



DRIVEN BY POSSIBILITY™


THE GATES eCRIMP APP - STEP BY STEP



STEP 1

SELECT YOUR LANGUAGE


The app is available in 9 languages (English, French, German, Russian, Chinese, Polish, Japanese, Spanish and Portuguese).

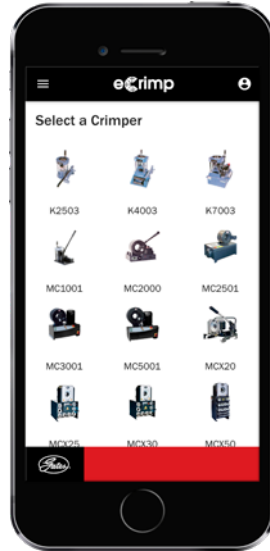

STEP 2

SELECT YOUR CRIMPER

Both currently sold MCX crimpers and legacy crimpers are listed.

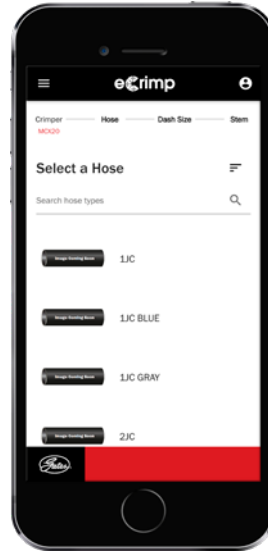

STEP 3

SELECT YOUR HOSE

Scroll down and select your hose or use the search option by typing in the hose, e.g. MXT.



STEP 4

SELECT THE INTERNAL DIAMETER OF THE HOSE


Select the internal diameter of the hose as listed in the catalogue or marked on the hose, e.g. 8MXT.



STEP 5

SELECT THE HOSE COUPLING


Select the right mating part. Only valid hose/coupling combinations will be listed.

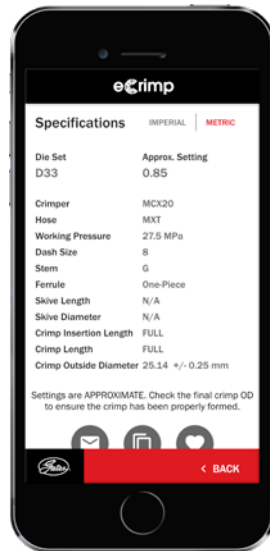

STEP 6

CRIMP DATA RECEIVED

Get ready to crimp! If needed, you can still switch the data from imperial to metric measurements or the other way around.

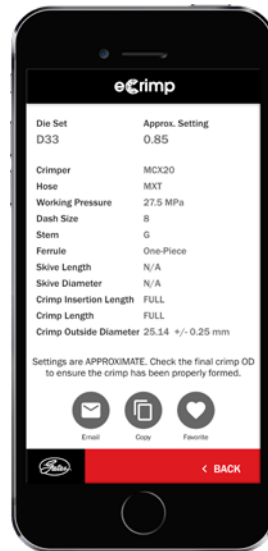

STEP 7

OPTIONAL

 
E-mail, copy or add the crimp data to your favourites by pressing the icons.



THE GATES eCRIMP WEBSITE - STEP BY STEP

STEP 1

GO TO ECRIMP.GATES.EU



STEP 2

SIMPLY DEFINE THE DESIRED SEARCH CRITERIA BY SELECTING THE REQUIRED ATTRIBUTES.

- Select your crimper
- Select you hose
- Select the internal diameter of the hose
- Optional: select the stem and/or die set

Enter Search Criteria

Search Hoses
 Search Hydraulic Hoses Search Industrial Hoses

Crimper	Die Set	Hose Description	Hose Dash Size	Stem Type
MCX001	D33	EFG5K-XTF	6	GS
MCX20		EFG5KL	8	
MCX25		EFG6K		
MCX30		EFG6K-MTF		
MCX50		EFG6KL		

Record Count: 1

STEP 3

CLICK THE "ADD RESULTS TO LIST" BUTTON TO VIEW THE REQUESTED CRIMP DATA.

STEP 4

BY CLICKING THE "PRINT RESULTS" BUTTON, YOU CAN PRINT THE TABLE OR POST IT FOR EASY REFERENCE ON A CRIMPER. THE SELECTED CRIMP DATA WILL BE CONVERTED TO A PRINTABLE PDF FORMAT.

MCX50 EFG6KL

Crimp and Machine Specifications for MCX25

Click on an underlined attribute name to sort by that column. Show English Units Show Metric Units

Show entries Search Description:

Hose				Stem	Ferrule	Specifications								
Dash Size	Description	Size (mm)	Working Pressure (MPa)	Type	Description	Skive Length (mm) (+/- 0.75)	Skive Diameter (mm)	Crimp Insertion Length (mm) (+/- 0.75)	Crimp Length (mm) (+/- 0.75)	Crimp Outside Diameter (mm)	Crimp Outside Diameter Tolerance (+/-)	Crimp Tail Length (mm) (+/- 2.5)	Die Set	Approximate Setting
8	EFG6K	12.0	42.0	8GS	08GS1F-4	NONE	NONE	FULL	FULL	27.45	0.25	NONE	D33	3.15

Showing 1 to 1 of 1 entries [remove](#)