



---

WEATHERLY NO.	400
CATALOG NO.	431-2061
EDITION	2019
SUPERSEDES	431-2061 (2016)

# GROUNDS MAINTENANCE EQUIPMENT

**COMMERCIAL & RESIDENTIAL LAWN  
AND GARDEN EQUIPMENT  
FARM & AGRICULTURAL EQUIPMENT**





Section	Pages
Table of Contents.....	A1
Warranty.....	A2
Product Pages.....	A3-A51
Abbreviations.....	A52
 <b>Application Listings</b>	
Riding Mowers.....	1-283
Walk Behind Mowers.....	284-347
Compact Tractors.....	348-351
Snow Blowers & Throwers.....	352-377
Tillers.....	378-441
Lawn Equipment.....	442-480
Lawn Attachments.....	481-535
Combines.....	536-539
Cotton Equipment.....	540-542
Harvesters.....	543-544
Hay Equipment.....	545-546
Sprayers.....	547-689
Tractors.....	548-690
Windrowers.....	690-694
 <b>Size Listings</b>	
Straight Hose Size List.....	695-697
Truflex® and PowerRated® V-Belts - by Size.....	698-699
BladeRunner® Belts - by Number.....	700-704
BladeRunner® Belts - by Size.....	705-708
FleetRunner® Micro-V® Belts - by Number.....	709-712
FleetRunner® Micro-V® Belts - by Size.....	713-715
Micro-V® Belts - by Number.....	716-722
Micro-V® Belts - by Size.....	723-727
Industrial Micro-V® Belts - by Number.....	728-731
FleetRunner® Heavy-Duty V-Belts - by Number.....	732
FleetRunner® Heavy-Duty V-Belts - by Size.....	733
XL® V-Belts - by Number.....	734-735
XL® V-Belts - by Size.....	736-737
Green Stripe® Truck and Bus V-Belts - by Number.....	738-739
Green Stripe® Truck and Bus V-Belts - by Size.....	740-741
Green Stripe® Truck and Bus PowerBand® V-Belts - by Number.....	742
Green Stripe® Truck and Bus PowerBand® V-Belts - by Size.....	743
Hi-Power II® V-Belts - by Number.....	744-745
Hi-Power II® PowerBand® Belts - by Number and Size.....	746
Super HC® V-Belts - by Number.....	747
Super HC® PowerBand® V-Belts - by Number.....	748
Tri-Power® V-Belts - by Number.....	749
Special Belts - by Number.....	750
Special Belts - by Size.....	751
Green Stripe® Vulco-Flex® Coolant Hose - by Number.....	752
Green Stripe® Vulco-Flex® Coolant Hose - by Size.....	753
Vulco-Flex II® Coolant Hose - by Number.....	754
Vulco-Flex II® Coolant Hose - by Size.....	755
 <b>Heavy-Duty to Standard Belt Interchange</b>	
FleetRunner® Micro-V® to Micro-V® Belt Interchange.....	756-757
FleetRunner® V-Belt to XL® V-Belt Interchange.....	758



## WARRANTY



### Warning

Be safe! Do not use Gates belts, pulleys or sprockets on any aircraft propeller or rotor drive systems or in-flight accessory drives. Those Gates products are not designed or intended for aircraft use.

### Caution

Use Gates products only on applications specified in Gates literature. Install and maintain products according to the vehicle manufacturers' recommended procedures and with recommended tools. Failure to follow these instructions could result in injury or property damage. Gates disclaims all liability due to failure to follow these instructions.


### Limited Warranty for the Life of the Merchandise

Goods are warranted to be free from defects in material or workmanship for the life of the Goods (or the published recommended replacement interval specified by Gates). Gates will replace or repair, at its option, any Goods proved defective in material or workmanship during the warranty period. This is the sole remedy for breach of warranty. Color fade and color difference is not warranted. This warranty is void if the defect is caused by improper installation, use or maintenance of the Goods, or used for racing or competition. Goods are not warranted to comply with laws that may apply to uses of the Goods not stated in related materials, e.g., use in manned or unmanned aviation or life support applications.

ALL OTHER WARRANTIES, EXPRESS OR IMPLIED, INCLUDING, BUT NOT LIMITED TO WARRANTIES OF MERCHANTABILITY AND FITNESS FOR A PARTICULAR PURPOSE, ARE EXPRESSLY DISCLAIMED. FAILURE TO REPLACE TIMING BELTS OR OTHER GATES PRODUCTS AS SPECIFIED MAY RESULT IN CATASTROPHIC ENGINE OR EQUIPMENT DAMAGE FOR WHICH GATES DISCLAIMS ALL RESPONSIBILITY, TO THE EXTENT PERMITTED BY APPLICABLE LAW.




### BLADERUNNER® BELTS

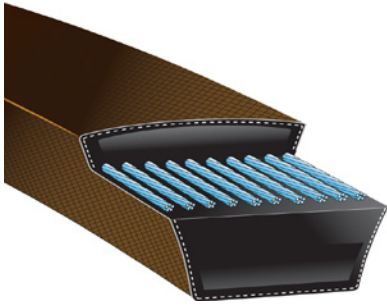

BladeRunner® belts are engineered to exactly match the composition, construction and fit of the original belts on the most common lawn and garden equipment. With superior durability and a wide range of SKUs, you'll find OEM-quality lawn & garden belts for top brand names.

- Aramid cord construction is utilized in many cases, providing longer service life during frequent and service shock loads.
- Built to withstand the rigorous start and stop operation of lawn and garden equipment.
- Meets or exceeds the performance of each specific application.
- Exact OEM fit and construction means more value and longer life.
- Reduces costly downtime and labor associated with replacing a belt.
- Smooth operation during frequent and severe shock loads.
- Superior performance over fractional horsepower belts on recommended applications.

### POWERATED® V-BELTS

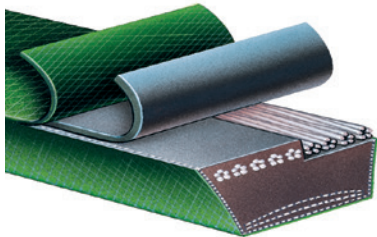


PoweRated® V-Belts are designed as an alternative to conventional light-duty belts, with high-performance construction to deliver more horsepower, less stretch, and provide longer service life. PoweRated belts are suitable for outdoor power equipment, appliances, and industrial applications where Fractional Horsepower (FHP) belts are typically used. They are recommended for heavy-duty drives and clutching applications. Meets the requirements of high power, clutching ability, heavy shock load absorption and back idler driven lawn and garden equipment.

- Meets RMA oil and heat-resistant standards, but not for static conductivity.
- Low cord positioning in thin profile gives extreme flexibility.
- Temperature Range: -22°F to +140°F (-30°C to +60°C).
- Product Type: 8423

**Note:** Gates PoweRated V-belts can be substituted for equivalent sizes of FHP low horsepower Gates Truflex® V-belts.

### TRUFLEX® V-BELTS

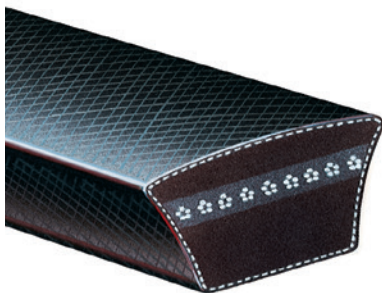

Truflex® belts are engineered with superior length stability for minimal take-up requirements, perfect for all industrial, light-duty applications, including fractional horsepower (FHP) motors and applications using backside idlers.

- Flex-bonded cords are strongly secured to the belt's body for equal load distribution and absorption of bending stress without cord deterioration.
- Gates Curves provide proper cord support and full contact with the sheave-groove for uniform loading, uniform wear, and increased belt life.
- The Flex-Weave® Cover is constructed for longer cover life, providing the belt's core with extended protection from oil, dirt, and heat.
- Runs with smooth, quiet operation.
- Meets RMA oil and heat-resistant standards and static conductivity requirements.
- Truflex belts are offered in cross sections 2L (0), 3L (1), 4L (2), 5L (3).
- Product Type: 8400

**Note:** Do not use on applications where FHP medium horsepower V-belts are recommended.






### SUPER HC® V-BELTS

Gates Super HC® V-belt combines the strength of a wrapped belt construction with the economies of a narrow section V-belt. It transmits more power in a given space and allows more compact drive design than classical section V-belts. In short, it offers you more power and considerably reduces the space needed. This significantly cuts the overall drive cost. Super HC V-belts also have exclusive Gates construction features for longer life on your drives.

- Up to 300% capacity increase over classical belts.
- Meets RMA oil and heat resistant standards and static conductivity requirements.
- Temperature Range: -22°F to +140°F (-30°C to +60°C).
- Product Type: 9332, 9334, and 9336.

**Gates also offers Super HC PowerBand® belts allowing multiple belts to function as a single unit with even load distribution and each strand fitting securely in the sheave groove.**

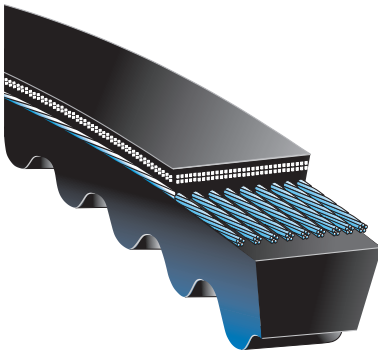

### SUPER HC® MOLDED NOTCH V-BELTS

When your power transmission application needs a high horsepower solution but is constrained by drive weight or physical space, the answer is Super HC® Molded Notch Belts. Our proprietary construction process provides a superior combination of flex and load-carrying capacity, transmitting up to three times the horsepower versus comparably sized belts. Super HC MN V-belts put more power where high speeds, high speed ratios or small pulley diameters are required, offering significant benefits over classical section V-belts. Developed through specialized research, Super HC MN is highly recommended for use on all industrial heavy-duty, narrow section V-belt drives. With increased transmission efficiency this belt allows for a more compact and highly economical drive design.

- Flex-bonded tensile cords are vulcanized as one solid unit making the belt highly resistant to tensile and flexing forces, fatigue and shock loads.
- Precision-ground straight sidewalls give a uniform wedging action and ensure the belt fits correctly in the pulley grooves.
- Molded Notches reduce and evenly distribute thermal and bending stresses.
- Meets ARPM/RMA IP-3-2 oil and heat resistance standards.
- Meets ARPM/RMA IP-3-3 static conductivity requirements.
- Temperature Range: -70°F to +250°F (-57°C to +121°C).
- Product Type: 9201

**Gates also offers Super HC Molded Notch PowerBand® V-belts allowing multiple belts to function as a single unit with even load distribution and each strand fitting securely in the sheave groove.**

### INDUSTRIAL MICRO-V® BELTS (J, L AND M SERIES)

Gates Micro-V® belts ensure outstanding performance on any industrial multi-ribbed drive. They cover a multitude of industrial applications and are suitable for industrial drives in washing machines, textile machines, vacuum cleaners, lawn mowers, machine tools, medical equipment and many more. The full line of Micro-V® belt products includes slabs in several widths as well as single belts in PJ, PK, PL and PM sections in order to perfectly match customer requirements. Gates Micro-V belts are an ideal choice for applications where space is at a premium, such as appliances, roller conveyors, machine tools, and medical equipment.



- Truncated ribs ensure flexibility, reduce heat build-up and improve rib crack resistance.
- Truncated ribs enhance load-carrying capacity on small diameter pulleys.
- High modulus, low stretch polyester tensile member provides superior resistance to fatigue and shock loads.
- Runs smoothly dampening vibration during high speed operation.
- Meets ARPM/RMA IP-3-2 oil and heat resistance standards.
- Meets ARPM/RMA IP-3-3 static conductivity requirements.
- Product Type: 9171, 9173, and 9174



### FLEETRANNER® MICRO-V® BELTS

FleetRunner® Micro-V® belts are engineered to save your fleet money and lost service time. Patented EPDM construction with distinct green overcord built specifically for more durability, superior flexibility, stability, and longer life on heavy-duty drives. Haul more. Drive longer.

- Patented material provides peak performance at prolonged extreme operating temperatures.
- Heavy-duty construction resists cracking and wear, even at extreme temperatures.
- Special compound provides unmatched flexibility, stability, load carrying capacity and belt life.
- Product Type: 8555



### FLEETRANNER® HEAVY-DUTY V-BELTS

Gates has coverage for hard-to-find belts used on specific lawn and garden applications, vintage vehicles and specialized equipment. Patented EPDM construction with distinct green overcord built specifically for more durability and longer life on heavy-duty drives.


- Outperforms the competition on the most troublesome drives.
- Special compound provides un-matched flexibility, stability, load carrying capacity and belt life.
- Patented material provides peak performance at extreme prolonged operating temperatures.
- Heavy-duty construction resists cracking and wear.
- Oil and heat-resistant.
- Unique undercord notch pattern offers increased flexibility for smaller diameter pulleys.
- Product Type: 8711




### GREEN STRIPE® POWERBAND® BELTS

Designed for problematic, heavy-duty, high-vibration applications that requires belt sets. The PowerBand® technology joins belts to operate as a single unit for improved stability and even load distribution, with a secure strand fit into the sheave groove.

- Unique tensile cord design gives belt extra strength, added flexibility, and shock-load resistance.
- Molded notches reduce bending stress, especially on small diameter pulleys, while dissipating heat.
- Even load distribution between strands provides better shock-load absorption.
- Belt cannot turn over or slip off drive.
- Meets or exceeds SAE J636 specifications.
- Product Type: 8541

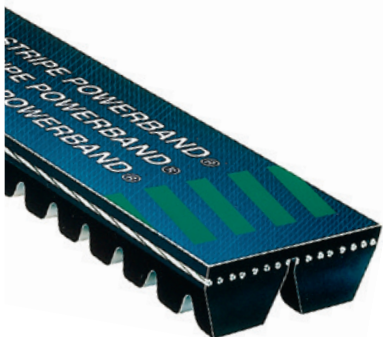

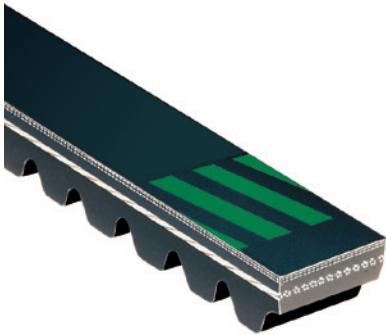


### GREEN STRIPE® TRUCK AND BUS SERIES V-BELTS

Specifically designed for heavy-duty truck, bus and off-road equipment applications. Absorbs normal shock loads without damage to belt. Its deep notch pattern also allows greater flexibility over small diameter pulleys and helps keep the belt cool. Special notch design resists cracking while providing tensile member support during operation.

- Special tensile cords give high stretch resistance.
- Oil and heat-resistant construction throughout.
- Meets SAE J636b and SAE J637 specifications.
- Product Type: 8620

**Gates also offers Green Stripe Truck and Bus Series PowerBand® V-belts for problem, heavy-duty, heavily vibrating applications requiring belt sets.**

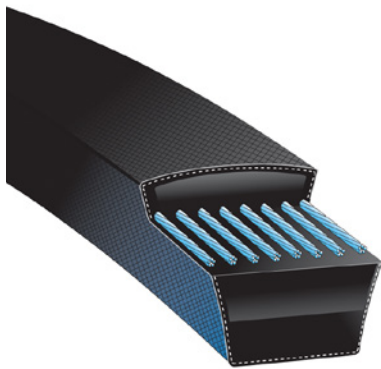


### HI-POWER® II V-BELTS

The wrapped classical section Hi-Power® V-belt has a long reputation for reliability on agricultural and industrial applications. The arched top of the Hi-Power belt provides superior strength to prevent "dishing" and distortion of the tensile section. The cords are properly aligned, each of them carrying its full share of the load.

- Arched top, concave sidewalls and rounded corners provide uniform tensile loading and uniform pulley sidewall contact for excellent belt service life and reduced pulley wear.
- The vulcanized Flex-bonded tensile cords provide superior resistance to tensile and flexing forces, fatigue and shock loads.
- The Flex Weave oil and heat resistant cover protects the belt core from the toughest environments.
- Meets ARPM/RMA IP-3-2 oil and heat resistance standards.
- Meets ARPM/RMA IP-3-3 static conductivity requirements.
- Product Type: 9002 - 9006

**Gates also offers Hi-Power II PowerBand® V-belts allowing multiple belts to function as a single unit with even load distribution and each strand fitting securely in the sheave groove.**

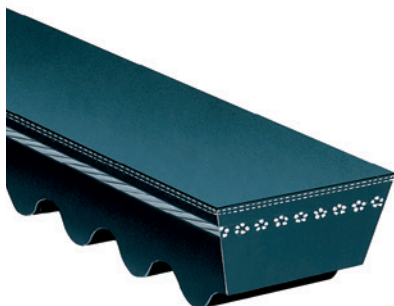

### TRI-POWER® BELTS

Gates Tri-Power® V-belt is built for superior performance on heavy duty drives of classical cross-section. The raw edge construction and special notch design makes the Tri-Power belt especially suited for drives requiring small diameter pulleys and back idlers. The patented ethylene EPDM compound construction allows the belt to resist cracking and handle extreme temperatures.

- Belt Edge is machined for even sheave groove contact, resulting in smoother running, less slip, and wear.
- Cross oriented fiber loaded rubber compound for flexibility and stability.
- Temperature Range: -58°F to +248°F (-50°C to +120°C).
- Meets ARPM/RMA IP-3-2 oil and heat resistance standards.
- Meets ARPM/RMA IP-3-3 static conductivity requirements.
- Product Type: 9012 - 9014

**Gates also offers Tri-Power II PowerBand® V-belts allowing multiple belts to function as a single unit with even load distribution and each strand fitting securely in the sheave groove.**





### XL® V-BELTS




The Automotive XL® is a durable, heavy-duty replacement V-belt designed for the most demanding engine drives. Due to thermal forces in the vehicle engine, this variable notched belt tightens on the drive as it heats up to prevent slippage or belt loss, improve belt performance, and reduce noise.

- Fiber-loaded rubber stock adds flexibility along the length of the belt and provides greater lateral stability in the pulley.
- Form-ground to ensure precise top width and sidewall dimensional control for proper fit to the pulley.
- Thermally active tensile cords for maintenance-free performance when properly installed and tensioned.
- XL Belts resist oil, heat, ozone, weather, and aging for improved belt life.
- Meets or exceeds SAE J636C specifications.
- Product Type: 8531 and 8701

**Gates also offers Green Stripe® XL V-belts as a premium-quality replacement for heavy-duty engines.**

### MICRO-V® BELTS

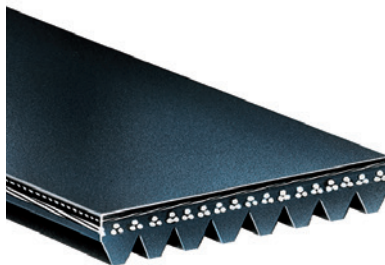


Import or domestic, car or truck, every vehicle can depend on the superior quality of Gates precision fit Micro-V® belts. With advanced technology that matches the OE size, construction and materials, Gates Micro-V ensures optimal vehicle performance. Micro-V belts provide peak operating performance while delivering the highest value on the market.

- Special belt construction eliminates belt noise, reduces tension loss, and solves problem drive applications.
- Utilizes advanced materials like Aramid Fiber found in bullet-proof vests and crack and heat-resistant EPDM materials.
- Meets or exceeds all specifications from the Original Equipment Manufacturer.
- Product Type: 8552


**Gates also offers Micro-V Green Stripe® belts with greater load-carrying capacity designed for demanding, heavy-service drives.**

### MICRO-V® ARAMID BELTS

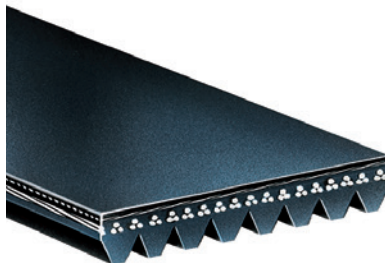

Gates, the leader in automotive serpentine belt drive systems, collaborates with OE manufacturers globally to continually evolve the performance and durability of belt drives. Certain vehicle engines require specific belt constructions, such as aramid tensile cord, to provide long belt life, and eliminate noise and vibration that are inherent on these drives. Utilizing this same technology for the Aftermarket, Gates offers an Aramid cord belt for specified vehicles. This construction matches the OEM to assure a quiet and smooth functioning belt, with the same performance and durability as the OEM part. For guaranteed OE performance, use Gates Micro-V® Aramid Serpentine Belts.

- Essential for specific demanding accessory belt drives (Turbo, Diesel, high RPM).
- Exact OEM aramid cord construction replacement - superior to polyester tensile cords that most serpentine belts come with.
- Extends life of the belt and other accessory drive components.
- Reduces noise, vibration and harshness (NVH).
- Product Type: 8626

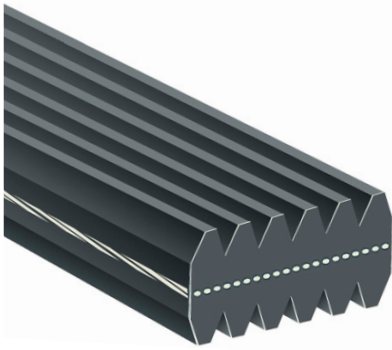

### MICRO-V® DUAL-SIDED BELTS

For replacing original equipment belts on serpentine drives that require a higher degree of efficiency when transmitting power. Designed for small diameter pulleys and for use with or without automatic tensioners.

- Specially designed to resist wear and cracking due to overall reduced thickness in construction.
- Broad coverage on unique applications.
- Custom setup for Gates specialized solution kits for Serpentine drives that cause problems from the OEM.
- Broad coverage on unique applications.
- V-ribbed on both sides of the belt.
- Product Type: 8550



### DRIVEALIGN® IDLER PULLEYS

Idlers that don't quit. Belt tension that won't slip. That's the Gates guarantee with our heavy-duty, wear-resistant idler pulleys and sprockets, designed to reduce wear, friction, and vibration on your drive system belts, ultimately extending your belt service life.

- Steel or thermoplastic construction provides high durability for long life.
- Bearing meets or exceeds OE and is designed for application specific speed and load requirements.
- Reliable operation under severe conditions.
- Applied for Import and Domestic vehicles.
- Mounting hardware included on some popular applications.
- Product Type: 7803



**HOSE SHELF LIFE**

Storage environment, along with rubber materials, can vary the shelf life limit. Shelf life is difficult to quantify as many variables affect the hose. Proper storage precautions can result in three to five years of shelf life. Beyond this time, there can be a significant service life decrease, depending on storage environment variables.

**Some variables include:** Hose should be stored in a cool, dry area never exceeding +100°F (+38°C). If stored below freezing, pre-warming may be required prior to handling, testing and placing into service. Store hose in original container. Never stack hose too high, as its weight can crush hose at the bottom of the stack. Gates recommends hose in extended storage be visually inspected and tested prior to use. Hose judged marginal should be replaced to avoid potential failure, property damage or bodily injury. Store hose on a first-in/first-out basis. Unusually long storage or poor storage environment can deteriorate hose, reduce performance and may lead to premature failure.



**ECR**  
ELECTROCHEMICAL  
RESISTANT

**MOLDED COOLANT HOSE**

Our molded coolant hoses are manufactured to fit upper, lower, bypass, heater and other coolant applications with OEM-quality specifications, saving you time, costs, and energy from going to your OE dealer for radiator hose replacements. Gates' curved hose line is the most comprehensive line on the replacement market.

- Engineered to resist electrochemical degradation, the leading cause of hose failure.
- Pre-shaped to fit and to ensure perfectly sealed conditions.
- Aramid or rayon knit reinforcement (depending on the application).
- Meets SAE 20R4 and 20R3 Type EC Class D-1 and D-2 specifications.
- Temperature Range: -40°F to +275°F (-40°C to +135°C) in coolant hose applications.
- Product Type: 4261

**Note:** Gates recommends replacing standard worm drive and spring loaded clamps with Gates PowerGrip® SB clamps each time a new coolant hose is installed.

**Caution:** Do not use for fuel or oil transfer applications..



**ECR**  
ELECTROCHEMICAL  
RESISTANT

**VULCO-FLEX® II COOLANT HOSE**

Gates Vulco Flex® II coolant hose is a flexible, durable curved hose designed to bend in almost any direction. The hose is engineered with improved sealing surface for greater leak resistance and easily replicates the angles and planes of a wide variety of expensive OE coolant hoses for quick, easy, and cost-effective replacement to virtually every vehicle on the road.

- Hose vulcanizes into shape without unnecessary strain on connections.
- Rated for SAE 20R5 Class D-2 performance.
- High temperature rating up to +257 °F (+125 °C).
- Product Type: 4254

**Note:** Gates recommends replacing clamps each time a new coolant hose is installed.

**Caution:** Do not use for fuel or oil transfer applications.

Part No.	I.D. (in.)	Length (in.)	Part No.	I.D. (in.)	Length (in.)	Part No.	I.D. (in.)	Length (in.)	Part No.	I.D. (in.)	Length (in.)
25150	1 1/8	12	25260	1 1/4	26 1/2	25409	1 3/8 x 1 1/2	26	25499	1 1/2	48
25152	1 1/8	15	25262	1 1/4	30	25428	1 3/8 x 1 5/8	17	25526	1 1/2 x 1 3/4	13 1/8
25154	1 1/8	18	25265	1 1/4	35	25472	1 1/2	8	25527	1 1/2 x 1 3/4	15
25157	1 1/8	23	25269	1 1/4	41	25473	1 1/2	10 1/2	25528	1 1/2 x 1 3/4	16 1/2
25180	1 1/8, 1 1/4	19	25284	1 1/4, 1 3/8	26	25474	1 1/2	12	25530	1 1/2 x 1 3/4	20
25249	1 1/4	7 1/2	25300	1 1/4 x 1 1/2	12	25476	1 1/2	14	25532	1 1/2 x 1 3/4	22
25250	1 1/4	9 1/2	25302	1 1/4 x 1 1/2	15 1/2	25477	1 1/2	15 1/2	25535	1 1/2 x 1 3/4	27
25251	1 1/4	13	25305	1 1/4 x 1 1/2	19 1/2	25478	1 1/2	17	25582	1 1/2 x 2	22
25252	1 1/4	15	25307	1 1/4 x 1 1/2	23	25480	1 1/2	20	25804*	1 1/2	20
25253	1 1/4	17	25309	1 1/4 x 1 1/2	26	25482	1 1/2	22	25806*	1 1/2	23 1/8
25254	1 1/4	18 1/2	25311	1 1/4 x 1 1/2	29	25484	1 1/2	25	25808*	1 1/2	25 5/8
25255	1 1/4	20	25321	1 1/4 x 1 1/2	44	25487	1 1/2	30			
25257	1 1/4	23	25384	1 3/8	25	25490	1 1/2	35			

\*90° Bend





**GREEN STRIPE® VULCO-FLEX® COOLANT HOSE**

Green Stripe® Vulco-Flex® hose can replace a multitude of curved hose sizes and shapes on a range of trucks, buses, and heavy-duty vehicles. Together with Gates' straight and curved radiator hoses, this flexible quality hose allows optimum market coverage. Flexible coolant hose with built-in spiral wire. It is a permanent replacement hose, equaling the performance of molded hose.



- Engineered to resist electrochemical degradation, the leading cause of hose failure.
- The built-in steel spiral allows for medium sized curves without kinking or collapsing.
- Polyester fabric ply reinforcement vulcanizes into shape without unnecessary strain on connections.
- Resistant to coolants, oil and ozone.
- Performs to SAE 20R5 Type EC Class D-2 specifications.
- Working Pressure: 40 psi maximum.
- Temperature Range: -40°F to +257°F (-40°C to +125°C).
- Product Type: 4284

**Caution:** Do not use for fuel or oil transfer applications.

Part No.	I.D. (in.)	Length (in.)	Part No.	I.D. (in.)	Length (in.)	Part No.	I.D. (in.)	Length (in.)	Part No.	I.D. (in.)	Length (in.)
26501	1¾	13 ½	26512	2	24	26523	2 ¼	19	26534	2 ¾	7
26502	1¾	16 ½	26513	2	33	26524	2 ¼	24	26535	2 ¾	14
26503	1¾ x 2	10	26514	2 x 2 ¼	8 ½	26525	2 ¼	27	26536	2 ¾	18
26504	1¾ x 2	16 ½	26515	2 x 2 ¼	15	26526	2 ¼ x 2 ½	18	26537	2 ¾	32
26505	1¾ x 2	19	26516	2 x 2 ¼	17 ½	26527	2 ¼ x 2 ½	21	26538	3	37
26506	1¾ x 2	23 ½	26517	2 x 2 ¼	25	26528	2 ¼ x 2 ½	25	26601	1¾	6
26507	2	9 ½	26518	2 x 2 ½	20	26529	2 ½	11	26602	1¾	8 ¼
26508	2	12 ¼	26519	2 ¼	9	26530	2 ½	14	26603	1¾	11
26509	2	14 ½	26520	2 ¼	11	26531	2 ½	16	26611	1¾	19
26510	2	17	26521	2 ¼	14	26532	2 ½	24	26612	1¾	23 ½
26511	2	20	26522	2 ¼	17	26533	2 ½	28			

**VULCO® STRAIGHT COOLANT HOSE**

Vulco® Straight Coolant Hose is specially engineered for straight coolant/air connections in automotive, stationary engine, industrial and home applications.



- Heat-resistant cover.
- Cover marked in one-inch increments for easy measuring and cutting allows "custom fit" light-duty coolant installations.
- Meets SAE 20R1 Standard Wall Class D-2 requirements.
- Temperature Range: -40°F to +257°F (-40°C to +125°C).
- Product Type: 4178

**Caution:** Do not use for fuel or oil transfer applications.

Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)	Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)	Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)
24008	½	105	24026	1 ⅝	55	24042	2 ⅝	30
24012	¾	80	24028	1 ¾	50	24044	2 ¾	30
24014	⅞	80	24030	1 ⅞	50	24046	2 ⅞	25
24016	1	75	24032	2	50	24048	3	25
24018	1 ⅛	75	24034	2 ⅛	45	24052	3 ¼	20
24020	1 ¼	65	24036	2 ¼	40	24056	3 ½	18
24022	1 ⅜	65	24038	2 ⅜	40	24064	4	12
24024	1 ½	60	24040	2 ½	35			



**ECR**  
ELECTROCHEMICAL  
RESISTANT

**WIRE-INSERTED GREEN STRIPE® COOLANT HOSE**

It's always best to have versatile solutions to ensure your various needs are met. Use the Wire Inserted Green Stripe® Coolant and Air Hose, which has the ability to replace many sizes of tailor-made, curved hoses. The cover cuts easily with a knife and wire cutters, ensuring the right length and easy installation.

- Heavy-duty fabric reinforcement with helical carbon steel wire.
- Engineered with compounds which resist electrochemical degradation.
- Exceeds SAE 20R2 Type EC (Class D2 Tube and cover) except in vacuum applications.
- Temperature Range: -40°F to +257°F (-40°C to +125°C).
- Product Type: 4685WG

**Note:** Long spans must be supported every 3 feet.

**Caution:** Do not use for fuel or oil transfer applications.

Part No. 5 ft.	Part No. 10 ft.	I.D.(in.)	Work. Press. (psi)	Vacuum (in. Hg.)	Min. Bend Radius (in.)
24916	28316	1	100	25	2
24918	—	1 1/8	100	25	2 1/2
24920	28320	1 1/4	100	25	2 1/2
24922	—	1 3/8	85	25	3
24924	28324	1 1/2	85	20	3 1/2
24926	28326	1 5/8	75	20	3 1/2
24928	28328	1 3/4	75	20	4
24930	28330	1 7/8	60	20	4 1/2
24932	28332	2	60	20	4 1/2
24934	—	2 1/8	55	20	5 1/2
24936	28336	2 1/4	55	20	5 1/2

Part No. 5 ft.	Part No. 10 ft.	I.D. (in.)	Work. Press. (psi)	Vacuum (in. Hg.)	Min. Bend Radius (in.)
24938	—	2 3/8	50	20	6 1/2
24940	28340	2 1/2	50	20	6 1/2
24942	—	2 5/8	40	15	7 1/2
24944	28344	2 3/4	40	15	7 1/2
24946	—	2 7/8	40	15	9
24948	28348	3	40	15	9
24956	28356	3 1/2	35	15	12
24964	—	4	30	10	20
24980	—	5	15	5	24
24996	—	6	15	5	30



**ECR**  
ELECTROCHEMICAL  
RESISTANT

**GREEN STRIPE® VIBRAFLEX® COOLANT HOSE**

When your heavy-duty applications require a shorter length hose that still needs to absorb vibration, a fitting misalignment, or possibly both, Gates has the perfect solution for you: the Green Stripe® Vibraflex® Hose. Its high flexibility reduces installation time and provides lower cost-per-mile operation.


- Oil and heat-resistant nitrile tube.
- Oil, abrasion and heat-resistant neoprene cover.
- Exceeds SAE J20 (Class B Tube and Class C Cover).
- Temperature Range: -40°F to +212°F (-40°C to +100°C).
- Product Type: 3177

**Caution:** Do not use for gasoline or diesel transfer applications.

Part No.	I.D. (in.)	Length (in.)	Work. Press. (psi)
23505	1 1/4	4	70
23511	1 3/8	5	60
23515	1 1/2	5	60
23520	1 3/4	5	55
23531	2	3 1/2	50
23533	2	5	50

Part No.	I.D. (in.)	Length (in.)	Work. Press. (psi)
23547	2 1/4	4 1/2	40
23557	2 3/8	5	35
23559	2 3/8	6 1/4	35
23562	2 1/2	4 1/2	35
23550	2 1/2	6	35
23566	2 3/4	3 1/4	30

Part No.	I.D. (in.)	Length (in.)	Work. Press. (psi)
23567	2 3/4	4 1/2	30
23568	2 3/4	5 3/8	30
23572	3	4	25
23575	3	7	25
23585	3 1/2	5 1/2	25

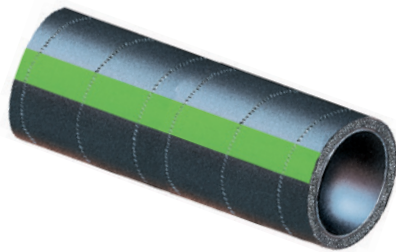

**EC/R**  
ELECTROCHEMICAL  
RESISTANT

**GREEN STRIPE® 2-PLY STRAIGHT COOLANT HOSE**

Green Stripe® 2-Ply Straight Coolant Hose stick hose is designed for demanding heavy-duty coolant/air applications. The two-ply bias fabric construction maximizes flexibility and strength, with an advanced EPDM tube and cover that resist "cold water leaks," and remain soft and pliable, even under adverse operating conditions.

- Cover marked in one-inch increments to facilitate approximate cut lengths, allows "custom-fit" installations.
- Engineered with compounds which resist electrochemical degradation.
- Exceeds SAE 20R1 Type EC (Class D-1 Tube, and cover, Standard Wall).
- Temperature Range: -40°F to +257°F (-40°C to +125°C).
- Product Type: 4168


**Note:** For a maintenance free connection, use PowerGrip® SB clamps.

**Caution:** Do not use for fuel or oil transfer applications.

Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)
24212	3/4	100
24214	7/8	100
24216	1	100
24218	1 1/8	100
24220	1 1/4	100
24222	1 3/8	100
24224	1 1/2	100
24226	1 5/8	85
24228	1 3/4	75

Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)
24230	1 7/8	75
24232	2	60
24234	2 1/8	60
24236	2 1/4	60
24238	2 3/8	60
24240	2 1/2	60
24242	2 5/8	60
24244	2 3/4	60
24246	2 7/8	55

Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)
24248	3	25
24250	3 1/8	25
24252	3 1/4	20
24256	3 1/2	18
24260	3 3/4	18
24264	4	12
24272	4 1/2	12

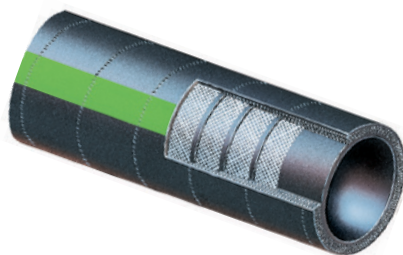

**EC/R**  
ELECTROCHEMICAL  
RESISTANT

**GREEN STRIPE® 4-PLY COOLANT HOSE**

For severe operating conditions found on stationary engines, construction equipment and off-road vehicle applications. Nitrile tube specially compounded to handle common coolants and additives. Four-ply woven, heavy-duty fabric reinforcement. Neoprene cover resists heat, abrasion and oil. Handles higher temperatures and resists petroleum additives. Reduces water loss from water permeating the hose wall and cover, a distinct advantage over silicone.

- Engineered with compounds which resist electrochemical degradation.
- Exceeds SAE 20R1 (Class B Tube, Class C Cover, Heavy Wall).
- Temperature Rating: -40°F to +212°F (-40°C to +100°C), intermittent to +257°F (+125°C).

**Caution:** Do not use for gasoline or diesel transfer applications.

Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)
24428	1 3/4	100
24430	1 7/8	100
24432	2	90
24434	2 1/8	90
24436	2 1/4	90
24438	2 3/8	90

Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)
24440	2 1/2	75
24442	2 5/8	75
24444	2 3/4	60
24446	2 7/8	60
24448	3	60
24450	3 1/8	60

Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)
24452	3 1/4	50
24456	3 1/2	50
24458	3 5/8	50
24460	3 3/4	50
24464	4	40
24480	5	40





**SILICONE COOLANT HOSE**

For your extremely high temperature radiator, heater, and coolant transfer applications, Gates Straight Silicone Coolant Hose is engineered with extra long-lasting silicone rubber for extreme ambient and radiant temperature conditions. The Silicone tube and cover resist prolonged exposure to under-hood and coolant heat, weathering, ozone, and deterioration. Use PowerGrip® SB clamps or silicone hose clamps to complete your assembly.

- Resists weathering, ozone, heat and coolant deterioration.
- Exceeds SAE 20R1 (Class A Standard Wall).
- Temperature Range: -70°F to +350°F (-56°C to +177°C).
- Product Type: 4171

**Note:** Silicone's water permeation rate is 10 to 15 times greater than Straight 2-Ply Coolant Hose.

**Caution:** Do not use for fuel or oil transfer applications.

Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)	Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)	Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)	Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)
24808	½	110	24820	1 ¼	85	24836	2 ¼	75	24852	3 ¼	40
24810	⅝	110	24822	1 ⅜	85	24838	2 ⅝	65	24856	3 ½	35
24812	¾	110	24824	1 ½	85	24840	2 ½	65	24860	3 ¾	35
24814	⅞	110	24826	1 ⅝	80	24844	2 ¾	50	24864	4	35
24816	1	90	24828	1 ¾	80	24848	3	50	24872	4 ½	25
24818	1 ⅛	90	24832	2	75	24850	3 ⅛	40			

**FLEETRANNER® HI-TEMP COOLANT HOSE**

FleetRunner® Hi-Temp Straight Coolant Hose is specifically designed for heavy-duty applications, trucks, buses, and off-road equipment, engineered with an advanced peroxide-cured EPDM material to provide exceptionally high temperature rating up to +300°F. The hose is tested in the toughest fleets, and with an OE-quality fit, function, and form that stands up to the most demanding driving environments.



- High working pressure rating provides protection for tough fleet and heavy-duty applications.
- Cover marked in 1" increments to facilitate approximate cut lengths and allows for "custom fit" applications.
- Engineered with compounds which resist electrochemical degradation.
- Advance peroxide-cured EPDM rubber.
- Exceeds SAE 20R1 specifications.
- Temperature Range: -40°F to +300°F (-40°C to +149°C).
- Product Type: 4175

Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)	Part No. 3 ft.	I.D. (in.)	Work. Press. (psi)
24614	⅞	150	24630	1 ⅞	150
24616	1	150	24632	2	150
24618	1 ⅛	150	24636	2 ¼	125
24620	1 ¼	150	24638	2 ⅝	125
24622	1 ⅜	150	24640	2 ½	125
24624	1 ½	150	24644	2 ¾	125
24626	1 ⅝	150	24648	3	125
24628	1 ¾	150			



**MOLDED SILICONE COOLANT HOSE**

Many heavy-duty vehicles manufactured in 2007 or later have advanced emissions systems that run hotter under the hood than previous models, requiring the use of a silicone coolant hose to maintain optimal temperatures. Gates Silicone Coolant Hose is perfect for areas in close proximity to high heat sources like the exhaust and turbo hot side, or where there is limited air flow around engines creating significantly high heat conditions.

- Premium 4-ply construction.
- High-heat resistance material meets or exceeds OE specifications.
- Product Type: 4177

Gates also offers application-specific molded silicone coolant hose for exact dimensional specifications.

**45° BENT (+350°F/+177°C)**

Part No.	I.D. (in.)	Arm Length (in.)
28205	1 ¾	6 x 6
28206	2	6 x 6
28207	2 ¼	6 x 6
28200	2 ½	6 x 6
28201	2 ¾	6 x 6
28202	3	6 x 6
28203	3 ½	6 x 6
28204	4	6 x 6

**90° ELBOW (+350°F/+177°C)**

Part No.	I.D. (in.)	Arm Length (in.)
28217	1 ¾	6 x 6
28210	2	6 x 6
28218	2	12 x 12
28211	2 ¼	6 x 6
28219	2 ¼	12 x 12
28212	2 ½	6 x 6
28220	2 ½	12 x 12
28213	2 ¾	6 x 6
28221	2 ¾	12 x 12
28214	3	6 x 6
28215	3 ½	6 x 6
28216	4	6 x 6

**HI-TEMP (+500°F/+260°C)**

Part No. 3 ft.	I.D. (in.)
28225	1
28226	1 ¼
28227	1 ½
28228	1 ¾
28229	2
28230	2 ¼
28231	2 ½
28232	2 ¾
28233	3

**90° MOLDED HEATER HOSE**



Molded Heater Hose designed for difficult heater hose applications requiring sharp 90° bends in the hose. These hoses eliminate the need for extensive inventory of OE type curved heater hose. Just 38 sizes handle thousands of applications.

- Engineered with compounds which resist electrochemical degradation.
- Resists water permeation.
- SAE 20R3 EC Class D1 under 25mm (1") ID, SAE 20R4 EC Class D1 for 25mm (1") ID or larger.
- Use with heater hose connectors and bulk heater hose for virtually complete molded heater hose coverage.
- Temperature Range: -40°F to +275°F (-40°C to +135°C).
- Product Type: 4257 and 4261


**Caution:** Do not use for fuel or oil transfer applications.

Part No.	I.D. (in.)	Arm Length (in.)
18010	¼	4 x 6
18011	¼	4 x 12
18020	⅙	4 x 6
18021	⅙	4 x 12
18030	⅜	4 x 6
18031	⅜	4 x 12
28460	½	4 x 6
28461	½	4 x 12
28462	½	4 x 18
28464	½	4 x 24

Part No.	I.D. (in.)	Arm Length (in.)
28465	½	4 x 36
28463	½	8 x 18
28466	⅝	4 x 6
28467	⅝	4 x 12
28468	⅝	4 x 18
28470	⅝	4 x 24
28471	⅝	4 x 36
28472	⅝	4 x 48
28473	⅝	4 x 60
28469	⅝	8 x 18

Part No.	I.D. (in.)	Arm Length (in.)
18079	⅝ x ¾	4 x 6
18076	⅝ x ¾	4 x 18
18077	⅝ x ¾	4 x 33
28474	¾	4 x 6
28475	¾	4 x 12
28476	¾	4 x 18
28477	¾	4 x 24
28479	¾	4 x 36
28480	¾	4 x 48
28481	¾	4 x 60

Part No.	I.D. (in.)	Arm Length (in.)
28478	¾	8 x 24
18070	¾ x ⅝	4 x 6
18071	¾ x ⅝	4 x 12
18073	¾ x ⅝	4 x 24
18074	¾ x ⅝	4 x 36
18075	¾ x ⅝	4 x 60
18072	¾ x ⅝	8 x 18
18078	¾ x ⅝	8 x 34

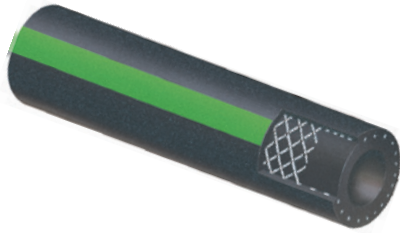


**GREEN STRIPE® HEATER HOSE**

With abrasion resistant, heavy-duty construction, Gates Green Stripe® Heavy-Duty Heater Hoses provide the best cost-per-mile economics for your truck, bus, and off-road equipment heater systems. The advanced EPDM tube, cover and reinforcement withstand high under-hood and coolant temperatures, designed and tested for extended use without cracking or hardening. Install Green Stripe Heater hose with PowerGrip® SB clamps for a maintenance-free connection.

- Green Stripe construction provides best cost-per-mile economics.
- Cover is abrasion resistant.
- Engineered with materials to resist electrochemical degradation.
- Reduces water loss from water permeating the hose wall and cover.
- Exceeds SAE 20R1 Type EC (Class D-1 Tube, and cover, Standard Wall).
- Temperature Range: -40°F to +275°F (-40°C to +135°C).
- Product Type: 3269

**Caution:** Do not use for fuel or oil transfer applications.

Part No. 50 ft.	Part No. 300 ft.	I.D. (in.)	Work. Press. (psi)
28436	—	3/8	105
28439	28440	1/2	105
28441	28447	5/8	95
28442	28448	3/4	80
28458	—	3/4	125
28443	—	7/8	80
28459	—	7/8	175
28444	28449	1	75
28445	—	1 1/4	70

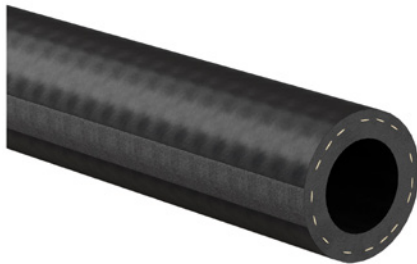

**SAFETY STRIPE® HEATER HOSE**

Get more out of your heater hose with a Safety Stripe® Heater Hose constructed for extra-long service life. Intended for use on cars and light trucks, this EPDM hose is unaffected by most coolants, non-oil based coolant additives, and high cooling system pressures. Additionally, it is resistant to high temperatures for extended periods of time, which aids in prolonging its service life, resulting in a more efficient engine.

- Not recommended for heavy-duty trucks, buses, or off-road construction equipment; use Green Stripe® heater hose for these applications.
- Meets SAE 20R3 Standard Wall Class D-2 requirements.
- Temperature Range: -40°F to +257°F (-40°C to +125°C).
- Product Type: 3270

**Caution:** Do not use for fuel or oil transfer applications.

**\*Gates also offers polybagged Safety Stripe Heater Hose that has self-service packaging for retail-oriented merchandising and fits standard pegboard displays. Package measures 12" wide x 13" high and hose comes in 6 foot lengths.**

Part No. 6 ft.*	Part No. 25 ft.	Part No. 50 ft.	Part No. 250 ft.	I.D. (in.)	Work. Press. (psi)
—	—	28407	—	1/4	60
—	—	24808	28423	5/16	60
28489	—	28409	—	3/8	60
28490	—	28410	—	1/2	60
28491	—	28411	28417	5/8	60
28492	—	28412	28418	3/4	50
—	28420	28413	—	1	45



**SILICONE HEATER HOSE**

Silicone Heater Hoses are constructed with silicone and reinforced with temperature-resistant, aramid textile cords, making them extremely durable and suited for high-temperature applications such as radiators, heaters, and other coolant transfer hose uses.


- High flexibility for versatile applications.
- High environmental resistance to weathering, coolant deterioration, and ozone.
- Suitable for emission hose applications.
- For proper installation, use Gates PowerGrip® SB clamps or Gates silicone hose clamps.
- Exceeds SAE 20R3 Class A Tube and Cover.
- Temperature Range: -70°F to +400°F (-57°C to +204°C).
- Product Type: 3230

**Caution:** Do not use for fuel or oil transfer applications.

Part No. 25 ft.	I.D. (in.)	Work. Press. (psi)
26239	3/8	60
26240	1/2	60
26241	5/8	60
26242	3/4	50
26244	1	45

**CHARTER® HEATER HOSE**

Economically priced heater hose – yet affords long service life. Tested by Gates to assure reliability.

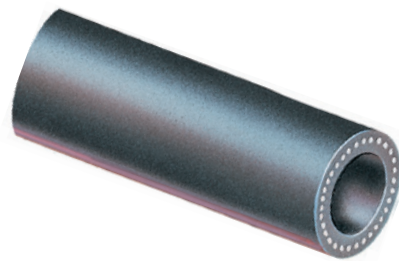

- Good resistance to high temperatures.
- Moderate resistance to oil and grease contamination.
- Good resistance to non-oil based coolant additives.
- Meets SAE 20R3 Standard Wall Class D-2 requirements.
- Temperature Range: -40°F to +257°F (-40°C to +125°C).
- Product Type: 3272

**Caution:** Do not use for fuel or oil transfer applications.

Part No. 50 ft.	Part No. 50 ft.	I.D. (in.)	Work. Press. (psi)
28400	28403	1/2	60
28401	28404	5/8	60
28402	28405	3/4	50






## DUAL I.D. HEATER HOSE

Gates Dual Inside Diameter, or Dual I.D., molded heater hose is designed for durable, long-lasting OE-quality performance on cars, light trucks, and other applications requiring diameter changes.

- Engineered with compounds which resist electrochemical degradation.
- Use with hose connectors and bulk heater hose for virtually complete molded heater hose coverage.
- Meets SAE 20R3 type EC Class D-1 and D-2 specifications.
- Temperature Range: -40°F to +275°F (-40°C to +135°C).
- Product Type: 4257

**Caution:** Do not use for fuel or oil transfer applications.

Part No.	I.D. (in.)	Length (in.)
18050	1/2 x 5/8	6
18051	1/2 x 5/8	12
18080	5/8 x 3/4	6
18081	5/8 x 3/4	12
18082	5/8 x 3/4	18
19351	5/8 x 3/4	24
18083	5/8 x 3/4	36
18084	5/8 x 3/4	60

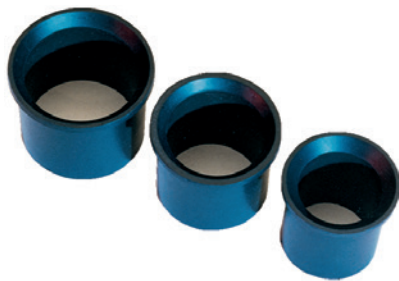

## HOSE I.D. REDUCERS

Slip inside current Gates hose to reduce inside diameters, providing maximum coverage with minimum hose inventory.

- Make it possible to adjust inside diameters of larger hoses for emergency replacements.
- Quality rubber construction assures maximum dependability, no leakage.
- Fits straight or flexible Gates coolant hoses.
- Product Type: 7736

**Caution:** Recommended for coolant and air applications only.

Part No.	Size (in.)
26390	1 1/2 to 1 1/4
26391	1 3/4 to 1 1/2
26392	2 to 1 3/4
26393	2 1/4 to 2
26394	2 1/2 to 2 1/4
26395	3 to 2 1/2



**PLASTIC HEATER HOSE AND FUEL LINE CONNECTORS**

Gates Heater Hose and Fuel Line Connectors use a unique single barb design to provide greater sealability between single or dual inside diameter hoses. Available in straight, 90° elbow and tee shapes - almost any hose configuration can be constructed.

- Glass reinforced nylon resists coolant additives, gasoline, diesel, oil and LPG.
- Bulkheads assure proper insertion depths.
- Anti-rotation device prevents hose twisting.
- Working pressure up to 2 MPa (20 kg/cm<sup>2</sup>).
- Resistance to extreme temperatures from -40°F to 480°F (-65°C to 250°C).
- Product Type: 7315

Gates also offers Fuel Hose Connector Assortment Part No. 91174 and Reducer Connector Assortment Part No. 91177.



**STRAIGHT CONNECTORS**

Part No.	O.D. (in.)
28561	3/32
28562	1/8
28563	5/32
28564	3/16
28600	5/16
28601	1/4
28602	3/8
28603	1/2
28604	5/8
28605	3/4
28606	1

**ELBOW CONNECTORS**

Part No.	O.D. (in.)
28571	3/32
28572	1/8
28573	5/32
28574	3/16
28621	1/4
28620	5/16
28622	3/8
28623	1/2
28624	5/8
28625	3/4
28626	1

**TEE CONNECTORS**

Part No.	O.D. (in.)
28581	3/32
28582	1/8
28583	5/32
28584	3/16
28631	1/4
28630	5/16
28632	3/8
28633	1/2
28634	5/8
28635	3/4
28638	1

**REDUCER CONNECTORS**

Part No.	O.D. (in.)
28591	3/32 to 1/8
28592	1/8 to 5/32
28593	3/16 to 1/4
28594	5/16 to 3/8
28609	3/8 to 1/2
28610	1/2 to 5/8
28611	5/8 to 3/4
28612	1 to 3/4
28639	5/16 to 1/2
28640	3/8 to 3/4

**TEE REDUCER CONNECTORS**

Part No.	End 1 O.D. (in.)	90° Tee O.D. (in.)	End 2 O.D. (in.)
28636	5/8	3/8	5/8
28637	3/4	3/8	3/4
28641	5/8	3/8	5/8
28642	1/2	1/4	1/2

**"Y" CONNECTORS**

Part No.	O.D. (in.)
28551	3/32
28552	1/8
28554	3/16



**POWERGRIP® SB CLAMPS**



Designed for your hose assemblies, Gates PowerGrip® SB Clamps are maintenance-free, durable hose clamps that retain dynamic tension for any shape of hose and housing, even on out-of-round fittings and applications, to reliably stop leaks without the need for re-tightening. The environmentally-friendly PowerGrip SB clamps are designed for a secure, tight fit in extreme operating temperatures to eliminate antifreeze leaks and groundwater contamination.

- Easy to install with ordinary heat gun.
- Wider sealing area entraps connector bead.
- Conform to any shape of hose and housing, even out-of-round fittings.
- Heat-sensitive thermoplastic with a memory to prevent over- or under-tightening.
- Can be used with all brands of silicone hose.
- Temperature Range: -40°F to +302°F (-40°C to +150°C).
- Product Type: 7405

Part No.	Size	Nominal Hose I.D. (in.)	Fits Hose O.D. (in.)
32915	SB15	¼	½ to 11/16
32919	SB19	⅜	11/16 to 13/16
32922	SB22	½	13/16 to 15/16
32925	SB25	5/8	15/16 to 1 1/16
32929	SB29	¾	1 1/16 to 1 3/16
32932	SB32	7/8	1 3/16 to 1 5/16

Part No.	Size	Nominal Hose I.D. (in.)	Fits Hose O.D. (in.)
32934	SB34	1	1 5/16 to 1 ½
32941	SB41	1 ¼	1 ½ to 1 ¾
32948	SB48	1 ½	1 ¾ to 2
32954	SB54	1 ¾	2 to 2 1/4
32960	SB60	2	2 ¼ to 2 ½

Part No.	Size	Nominal Hose I.D. (in.)	Fits Hose O.D. (in.)
32967	SB67	2 ¼	2 ½ to 2 ¾
32973	SB73	2 ½	2 ¾ to 3
32979	SB79	2 ¾	3 to 3 ¼
32986	SB86	3	3 ¼ to 3 ½
32990	SB90	3 ⅝	3 ½ to 3 ¾

**GREEN STRIPE® STAINLESS STEEL CLAMPS**



Green Stripe® Stainless Steel Clamps are the perfect solution for work with industrial machinery or in applications where corrosion is likely to become an issue. The durable clamps and screws, both made of heavy-gauge stainless steel, are a dependable and long-lasting pair.

- Housing and 9/16" wide band are constructed of heavy-gauge stainless steel.
- Tightening screw is a 400 series stainless steel screw.
- Rounded band edges give your hoses extra protection.
- Hex-shaped screw has a deep slot that tightens with screwdriver, nut driver, or socket wrench.
- Tighten to 35 in. lb.
- Product Type: 7408

Part No.	Size	Fits Hose I.D. (in.)	Clamping Range (in.)
32201	4	5/32 to 1/2	1/4 to 5/8
32207	7	7/32 to 11/16	5/16 to 7/8
32210	10	3/8 to 5/8	1/2 to 1 1/8
32212	12	5/8 to 3/4	1/2 to 1 1/4
32216	16	3/4 to 1	3/4 to 1 1/2
32220	20	1 to 1 1/4	3/4 to 1 3/4
32224	24	1 1/4 to 1 1/2	1 to 2
32228	28	1 1/4 to 1 3/4	1 5/16 to 2 1/4
32232	32	1 1/2 to 2	1 9/16 to 2 1/2

Part No.	Size	Fits Hose I.D. (in.)	Clamping Range (in.)
32236	36	1 1/2 to 2 1/4	7/8 to 1 7/8
32248	48	2 1/2 to 3	1 5/8 to 3 1/2
32252	52	2 1/2 to 3 1/4	1 7/8 to 3 3/4
32256	56	2 to 3 1/2	2 1/8 to 4
32260	60	2 1/2 to 3 3/4	2 5/16 to 4 1/4
32264	64	2 1/4 to 4	2 5/8 to 4 1/2
32272	72	3 to 4 1/2	3 1/8 to 5
32304	104	4 to 6 1/2	4 to 7



**SUPER HEX/MINEX CLAMPS**

Top quality clamp with extra-strength construction. Super Hex features a 1/2" wide band, while the Minex band is 5/16".

- Durable 200 series stainless steel band and screw housing.
- One-piece screw housing is interlocked onto band for extra strength.
- Solid head forged from one piece of steel, cadmium plated.
- Hex-shaped screw has a deep slot that tightens with screwdriver, nut driver, or socket wrench.
- Meets SAE J1508.
- Tighten to 30 in. lb.
- Product Type: 7400

Part No.	Size	Fits Hose I.D. (in.)	Clamping Range (in.)
32001*	1	5/32 to 1/2	1/4 to 5/8
32006	6	1/4 to 3/8	3/8 to 7/8
32007*	7	7/32 to 11/16	5/16 to 7/8
32008	8	5/16 to 1/2	7/16 to 1
32010	10	3/8 to 5/8	1/2 to 1 1/8
32012	12	5/8 to 3/4	1/2 to 1 1/4
32016	16	3/4 to 1	3/4 to 1 1/2
32020	20	1 to 1 1/4	3/4 to 1 3/4
32024	24	1 1/4 to 1 1/2	1 to 2
32028	28	1 1/4 to 1 3/4	1 5/16 to 2 1/4

Part No.	Size	Fits Hose I.D. (in.)	Clamping Range (in.)
32032	32	1 1/2 to 2	1 5/16 to 2 1/2
32036	36	1 3/4 to 2 1/4	7/8 to 2 3/4
32040	40	2 to 2 1/2	1 1/8 to 3
32044	44	2 1/4 to 2 3/4	1 5/16 to 3 1/4
32048	48	2 1/2 to 3	1 5/8 to 3 1/2
32052	52	3 to 3 1/4	1 7/8 to 3 3/4
32056	56	2 to 3 1/2	2 1/8 to 4
32064	64	2 1/4 to 4	2 5/8 to 4 1/2
32072	72	3 to 4 1/2	3 3/8 to 5
32104	104	4 to 6 1/2	4 to 7

\*Minex

Type of Clamp	Recommended Installation Torque	Maximum Torque
Minex	14-16 in. lb.	20 in. lb.
Super Hex + Charter	25-35 in. lb.	50 in. lb.
Green Stripe® Stainless Steel, Silicone + Marine	30-40 in. lb.	60 in. lb.



**GREEN STRIPE® MARINE CLAMPS**

Constructed of 100 percent marine grade stainless steel. Bands are 9/16" wide with rounded edges. Screws feature 300 series stainless steel construction and deep slotted 5/16" hex heads.

- Saline and corrosion-resistant.
- Product Type: 7408

Part No.	Size	Fits Hose I.D. (in.)	Clamping Range (in.)
32508	8M	5/16 to 1/2	7/16 to 1
32510	10M	3/8 to 5/8	1/2 to 1 1/8
32512	12M	5/8 to 3/4	1/2 to 1 1/4
32516	16M	3/4 to 1	3/4 to 1 1/2
32520	20M	1 to 1 1/4	3/4 to 1 3/4
32524	24M	1 1/4 to 1 1/2	1 to 2
32528	28M	1 1/4 to 1 3/4	1 5/16 to 2 1/4
32532	32M	1 1/2 to 2	1 9/16 to 2 1/2

Part No.	Size	Fits Hose I.D. (in.)	Clamping Range (in.)
32536	36M	1 3/4 to 2 1/4	1 7/8 to 2 3/4
32548	48M	2 1/2 to 3	1 5/8 to 3 1/2
32552	52M	3 to 3 1/4	1 7/8 to 3 3/4
32556	56M	2 to 3 1/2	2 1/8 to 4
32560	60M	2 1/4 to 3 3/4	2 5/16 to 4 1/4
32564	64M	2 1/4 to 4	2 5/8 to 4 1/2
32572	72M	3 to 4 1/2	3 1/2 to 5
32604	104M	5 to 6 1/2	5 to 7





**SILICONE HOSE CLAMPS**

Silicone Hose Clamps provide an extra-tight seal on silicone hose and prevent hose cover extrusion. We've engineered our hose clamps with durable, high-strength stainless steel band, screw, and housing to resist corrosion and withstand tough operating conditions.

- 300 series stainless steel band, screw and housing resist corrosion.
- Four-piece construction and 100% mechanical interlock for added strength and torque capability.
- One piece band and liner.
- Wide 9/16" band gives 12 1/2 more compression than 1/2" band.
- Hex-shaped screw has a deep slot that tightens with screwdriver, nut driver, or socket wrench.
- Tighten to 35 in. lb.
- Product Type: 7400

Part No.	Size	Fits Hose I.D. (in.)	Clamping Range (in.)
32308	8	5/16 to 1/2	7/16 to 1
32310	10	3/8 to 5/8	3/4 to 1 1/8
32312	12	5/8 to 3/4	7/8 to 1 1/4
32316	16	3/4 to 1	1 to 1 1/2
32320	20	1 to 1 1/4	1 1/8 to 1 3/4
32324	24	1 1/4 to 1 1/2	1 1/4 to 2
32328	28	1 1/4 to 1 3/4	1 5/8 to 2 1/4
32332	32	1 1/2 to 2	1 9/16 to 2 1/2

Part No.	Size	Fits Hose I.D. (in.)	Clamping Range (in.)
32336	36	1 3/4 to 2 1/4	1 13/16 to 2 3/4
32340	40	2 to 2 1/2	2 1/8 to 3
32344	44	2 1/4 to 2 3/4	2 15/16 to 3 1/4
32348	48	2 1/2 to 3	2 9/16 to 3 1/2
32352	52	3 to 3 1/4	2 13/16 to 3 3/4
32356	56	3 1/4 to 3 1/2	3 1/8 to 4
32364	64	3 3/4 to 4	3 9/16 to 4 1/2
32372	72	4 to 4 1/2	4 1/8 to 5



**GREEN STRIPE® HEAVY-DUTY T-BOLT CLAMPS AND SPRING LOADED T-BOLT CLAMPS**

When you need to keep your operation running, whether you're repairing medium or heavy-duty truck systems, off-road equipment, or industrial applications, keep your hoses in place Green Stripe® Heavy-Duty T-Bolt Clamps. Our heavy-duty clamps were designed for use in heavy-vibration environments and large diameter applications to seal liquid or air connections on hoses.

- Recommended installation torque: 75 in. lb.
- Product Type: 7422



**GREEN STRIPE SPRING-LOADED T-BOLT CLAMPS**

Part No.	Size	Clamping Range (in.)
32861	70	3 1/16 to 3 3/8
32862	86	3 3/16 to 3 7/8
32863	102	4 1/16 to 4 3/8
32864	118	4 3/16 to 4 7/8

**GREEN STRIPE T-BOLT CLAMPS**

Part No.	Size	Clamping Range (in.)
32749	-	1 3/8 to 1 9/16
32750	-	1 1/2 to 1 5/8
32751	-	1 5/8 to 1 7/8
32752	28	1 3/4 to 2
32753	32	1 7/8 to 2 3/16
32754	36	2 to 2 5/16
32755	40	2 1/8 to 2 7/16
32756	44	2 1/4 to 2 9/16
32757	48	2 3/8 to 2 11/16
32758	52	2 1/2 to 2 13/16
32759	56	2 5/8 to 2 15/16
32760	60	2 3/4 to 2 1/16
32761	64	2 7/8 to 3 1/16

Part No.	Size	Clamping Range (in.)
32762	68	3 to 3 5/16
32763	72	3 1/8 to 3 7/16
32764	76	3 1/4 to 3 9/16
32765	80	3 3/8 to 3 11/16
32766	84	3 1/2 to 3 13/16
32767	88	3 5/8 to 3 15/16
32768	92	3 3/4 to 4 1/16
32769	100	4 to 4 5/16
32770	108	4 1/4 to 4 9/16
32771	116	4 1/2 to 4 13/16
32772	124	4 3/4 to 5 1/16
32773	132	5 to 5 5/16
32774	140	5 1/4 to 5 9/16

Part No.	Size	Clamping Range (in.)
32775	148	5 1/2 to 5 13/16
32776	156	5 3/4 to 6 1/16
32777	164	6 to 6 5/16
32778	172	6 1/4 to 6 9/16
32779	180	6 1/2 to 6 13/16
32780	188	6 3/4 to 7 1/16
32781	196	7 to 7 5/16
32782	204	7 1/4 to 7 9/16
32783	212	7 1/2 to 7 13/16
32784	220	7 3/4 to 8 1/16
32785	228	8 to 8 5/16
32786	236	8 1/4 to 8 9/16
32787	244	8 1/2 to 8 13/16



**GREEN STRIPE® AND GREEN STRIPE® HEAVY-DUTY CONSTANT TENSION CLAMPS**

Green Stripe® constant tension clamps provide the reusable, self-adjusting band needed for a dependable seal, even in the coldest conditions. The Green Stripe and Green Stripe Heavy-Duty constant tension clamps feature larger, heavy-gauge, precision-formed spring washers with higher rates of band tension and adjustability for a more dependable seal for use in automotive, truck, and bus cooling systems and turbochargers.

- All stainless steel construction for maximum corrosion resistance.
- Band and housing – 9/16" wide GSCT 301 and 5/8" wide GSHD 304 stainless steel.
- Hex-head screw – 410 stainless steel GSCT 5/16" and GSHD 3/8" wide.
- A uniform 360° seal.
- Clamping diameters – GSCT 9/16" to 3 1/2" and GSHD 1" to 9 1/8".
- Tighten Green Stripe clamps to minimum of 50 in. lb. and maximum of 85 in. lb., and heavy-duty clamps to minimum of 75 in. lb. and maximum of 125 in. lb.
- Product Type: 7408GSCT and 7408GSHD

**GREEN STRIPE® CONSTANT TENSION CLAMPS  
301 STAINLESS STEEL 9/16" BAND AND HOUSING  
410 STAINLESS STEEL 5/16" HEX-HEAD SCREW**

Part No.	Size	Clamping Range (in.)
32710	10	5/16 to 1 1/16
32712	12	5/8 to 1 1/4
32716	16	13/16 to 1 1/2
32720	20	13/16 to 1 3/4
32724	24	1 1/16 to 2
32728	28	1 5/16 to 2 1/4
32732	32	1 9/16 to 2 1/2
32736	36	1 13/16 to 2 3/4
32740	40	2 1/16 to 3
32744	44	2 5/16 to 3 1/4
32748	48	2 9/16 to 3 1/2

**GREEN STRIPE® HD CONSTANT TENSION CLAMPS  
304 STAINLESS STEEL 5/8" BAND AND HOUSING  
410 STAINLESS STEEL 3/8" HEX-HEAD SCREW**

Part No.	Clamping Range (in.)
32617	1 to 1 3/4
32620	1 1/4 to 2 1/8
32625	1 3/4 to 2 3/8
32630	2 1/4 to 3 1/8
32635	2 3/4 to 3 3/8
32640	3 1/4 to 4 1/8
32645	3 3/4 to 4 5/8
32650	4 1/4 to 5 1/8
32655	4 3/4 to 5 5/8
32660	5 1/4 to 6 1/8
32665	5 3/4 to 6 5/8
32670	6 1/4 to 7 1/8
32675	6 3/4 to 7 5/8
32680	7 1/4 to 8 1/8
32685	7 3/4 to 8 5/8
32690	8 1/4 to 9 1/8



### OE TYPE THERMOSTATS

Gates only partners with prime OE thermostat manufacturers to provide OE Exact or OE Type construction.



- Map Controlled - Bolt-on solution with included sensor that links to the engine control unit.
- Same easy installation as standard ITH.
- Allows ECU to regulate engine temperatures.
- Provides adaptive, on-demand engine cooling.
- Lowers emissions and fuel consumption.
- Quality controlled factory calibration assures accuracy of opening and closing, regardless of pressure changes.
- Matches the OEM product fit, function and design.
- Features including jiggle pins and check valves for air venting, seals and gaskets make these thermostats equivalent to the original equipment parts.
- Easy, one step fit and installation with no special tools required.
- Category-leading vehicle coverage.
- Product Type: 7412

⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)



### THERMOSTAT GASKETS

Cuts installation time in half. Adhesive-backed gasket material helps prevent breaking of water outlet. Gasket cement is not needed.

- Self-adhesive backing holds thermostat in place while water outlet is being installed.
- Rubber thermostat seals also available.
- Product Type: 7413

### GREEN STRIPE® HEAVY-DUTY THERMOSTATS

Gates only partners with prime OE thermostat manufacturers to provide OE Exact or OE Type construction for use on heavy-duty trucks, buses and tractors.



- Heavy-gauge brass and stainless steel with positive piston heat motor.
- Fits applications with 3/4" deep filler necks. Custom heavy-duty radiator caps available upon request.
- Quality controlled factory calibration assures accuracy of opening and closing, regardless of pressure changes.
- Matches the OEM product fit, function and design.
- Temperature sensitive heat motor provides consistent valve response for smooth performance and precise engine cooling.
- Features including jiggle pins and check valves for air venting, seals and gaskets make these thermostats equivalent to the original equipment parts.
- Product Type: 7412

**Note:** Seal should always be changed when new thermostat is installed.

⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)



## GREEN STRIPE® HEAVY-DUTY THERMOSTAT SEALS

Fits securely around thermostat valve to prevent leakage.

- Corrosion-resistant steel construction.
- Specially constructed to assure accurate fit.
- Product Type: 7412



## HEAVY-DUTY RADIATOR CAPS

For use on heavy-duty trucks, buses and tractors. Fits applications with 3/4" deep filler necks.

- All Gates radiator pressure caps are constructed of corrosion-resistant, heavy-gauge metal to assure long service life and accurate pressure control.
- Covers a wide range of pressures.
- Designed and manufactured to OE standards.
- No adjustment required for installation.
- Precise pressure control.
- Product Type: 7410

⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)



## RADIATOR CAP AND COOLING SYSTEM ANALYZER KIT

Contains all components needed to check cooling systems and radiator caps.

- Lightweight, impact-resistant analyzer.
- Pressure release button on easy-to-read gauge allows for safe venting of system during testing.
- Kit Part No. 31367\* includes Part No. 31425, 31413\*, and carrying case.

⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)



## RADIATOR CAP/COOLING SYSTEM TESTER ADAPTERS

For use with Radiator and Fuel Cap Testers.

- Covers a wide range of pressures.
- Product Type: 7410

⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)





**BARRICADE® FUEL INJECTION HOSE (MPI)**



Barricade® fuel injection hose is a low permeation, multi-fuel compatible hose that virtually eliminates fuel vapor loss thanks to our 5-layer GreenShield® barrier technology. Works with multiple fuels (approved for use with leaded and unleaded petrol, diesel, biodiesel up to B-100, E-10, E-15, E-85, 100% methanol, ethanol and gasohol fuels).

- Fuel savings from Barricade's incredibly low permeation rate - the lowest on the market at 1g/m2/day.
- Easily complies with environmental standards, exceeds the requirements of SAW J30R14T2 (except for kink resistance).
- Working Pressure: 225 psi.
- Temperature Range: -40°F to +275°F (-40°C to +135°C) continuous, up to +302°F (+150°C) intermittent.
- Product Type: 4219BF

**Note:** Do not submerge in gasoline.

Part No. 2 ft.	Part No. 15 ft.	Part No. 25 ft.	Part No. 250 ft.	I.D. (in.)
27334	27347	27339	27344	¼
27335	27348	27340	27345	⅝
27336	27349	27341	27346	⅜
—	—	27342	—	½

**BARRICADE® CARBURETION HOSE**



Advanced fuel formulations require a fuel hose that's up to the task. Barricade® Carburetion hose provides a premium, low-permeation hose solution compatible for use with many fuel systems and fuel types. Barricade Fuel Injection Hose are made with Gates' patented five-layer Greenshield® technology, providing exceptional performance and fuel efficiency. This environmentally-friendly hose solution provides five times less permeation than the nearest competitor.

- HNBR tube with thermoplastic barrier and CPE cover; reinforced aramid fiber.
- Meets SAE 30R14 T1, CARB & EPA non-road fuel lines.
- Multi-fuel compatibility.
- Oil, heat, ozone, and abrasion-resistant cover.
- Not for use on pressure lines of fuel injection or cooling system applications.
- High temperature range tolerance: -40°F to +257°F (-40°C to +125°C).
- Product Type: 4219BG


**Note:** Do not submerge in gasoline.

**Caution:** Do not use on pressure lines on fuel injection systems or cooling system applications. Use Barricade Fuel Injection (Product Type 4219BF) hose for Multi-Port Injection systems.

Part No. 2 ft.	Part No. 25 ft.	Part No. 250 ft.	I.D. (in.)	Work. Press. (psi)
27302	27312	27321	⅜	50
27303	27313	27323	¼	50
27304	27314	27324	⅝	50
27305	27315	27325	⅜	50
27306	27316	27326	½	35



**SAFETY STRIPE® RETURN FUEL LINE/PCV/EVAPORATIVE EMISSION CONTROL HOSE (1986 & OLDER)**

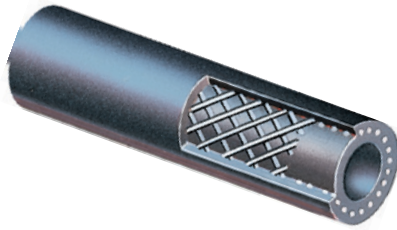

Multi-purpose hose for use on return fuel lines, PCV and EEC systems, and for fuel return hose connections on diesel fuel injection systems. Approved for use with leaded and unleaded gasoline, diesel and gasoline blends of ethanol (E85), methanol and ethers (up to the legal limits allowed by the EPA).

- Spiral reinforced construction.
- Tube has been upgraded to meet changes in fuel characteristics and resists heat and oil.
- Working pressure up to 1 Mpa (10kg/cm2).
- Meets requirements of SAE J30R7 and DIN 73379 (except for tolerances).
- Temperature Range: -40°F to +257°F (-40°C to +125°C) with gasoline blends.
- Product Type: 4219XL

**Caution:** Do not use for pressure lines on fuel injected engines or for cooling system applications. Use Barricade® Fuel Injection hose for fuel injection applications. Intended for use with fuels where MTBE concentrations are no greater than 15% by volume.

**\*Gates also offers packaged Safety Stripe Return Fuel Line hose in convenient, popular two foot lengths of hose in self-service, reusable, recyclable package. Can be stacked on shelf or hung on a pegboard display. Handy hose diameter indicator helps customer select the correct size.**

Part No. 2 ft.*	Part No. 25 ft.	Part No. 250 ft.	I.D. (in.)	Work. Press. (psi)
—	27000	27099	1/8	50
—	27001	27098	3/16	50
27027	27002	27068	1/4	50
27028	27003	27069	5/16	50
27029	27004	27070	3/8	50
—	27005	27071	7/16	35
—	27006	27019	1/2	35
—	27008	27020	5/8	35
—	27010	27021	3/4	35

**FUEL FILL HOSE**

Designed for transferring fuel from vehicle's filler neck to fuel tank. Works on passenger cars and light trucks, as well as on auxiliary fuel tanks on recreational vehicles. For use with most types of fuels – especially resistant to gasoline and diesel.



- Suitable for use with gasoline, gasohol blends of ethanol, methanol, ethers, diesel and bio-diesel to B20 (up to maximum concentrations allowed by the EPA).
- Features a high quality nitrile tube.
- Meets requirements of SAE 30R5.
- Cuts easily with knife and wire cutters.
- Working Pressure: 20 psi.
- Temperature Range: -40°F to +212°F (-40°C to +100°C) with gasoline blends, -40°F to +125°F (-40°C to +51°C) with bio-diesel (B20).
- Product Type: 4663

**Note:** Use Gates Super Hex clamps for reliable installation.

Part No. 3 ft.	I.D. (in.)	Part No. 3 ft.	I.D. (in.)
23924	1 1/2	23936	2 1/4
23930	1 7/8	23940	2 1/2
23932	2		



**FUEL FILLER NECK HOSE**

Designed specifically for auxiliary gas tanks on recreational vehicles. Excellent replacement for passenger cars and trucks where a straight hose with a minimal bend is required. Suitable for use with gasoline, gasohol blends of ethanol, methanol, ethers, diesel and biodiesel to B20 (up to maximum concentrations allowed by the EPA). Angled Fuel Fill Hose is designed for tank fuel fill connections where straight hose will not work.



- Smooth oil resistant cover, tough textile cord reinforcement and petroleum-resistant nitrile tube.
- Non-wire reinforced.
- Meets SAE 30R6 specifications.
- Temperature Range: -40°F to +212°F (-40°C to +100°C) with gasoline blends, -40°F to +125°F (-40°C to +51°C) with bio-diesel (B20).
- Product Type: 4271 and 4278

**Caution:** Not recommended for marine gasoline applications.

**STRAIGHT:**

Part No.	I.D. (in.)	Length (ft.)	Work. Press. (psi)
23963	1 ¼	3	20
24702	1 ¾	3	20
24703	1 ½	1 ½	20
23964	1 ½	3	20
24704	1 ¾	1 ½	20
23968	1 ¾	3	20
24705	2	1 ½	20
23972	2	3	20
23976	2 ¼	3	20
23980	2 ½	3	20

**45° BEND:**

Part No.	I.D. (in.)	Length (ft.)	Work. Press. (psi)
24710	1 ½	15 7/8	20
24711	1 ¾	15 7/8	20
24712	2	15 7/8	20
24713	2 ¼	15 7/8	20
24714	2 ½	15 7/8	20

**90° BEND:**

Part No.	I.D. (in.)	Length (ft.)	Work. Press. (psi)
24715	1 ½	15 ½	20
24716	1 ¾	15	20
24717	2	14 7/8	20
24718	2 ¼	14 5/8	20
24719	2 ½	14 5/8	20

**62° BEND:**

Part No.	I.D. (in.)	Length (ft.)	Work. Press. (psi)
24721	1 ½	17 4/9	16

**SUBMERSIBLE FUEL LINE HOSE**

If your in-tank applications and fuel systems cause your hoses to be in constant contact with gasoline or other fuel fluids, you need the Gates Submersible Fuel Hose. Most fuel lines are only designed to handle fuel on the interior of the hose, which can be damaged if the exterior is exposed to fuel. Gates Submersible Fuel Line Hose is capable of handling multiple types of gasoline and fuels, including gasoline, alcohol-extended gasoline, ethanols, biodiesel or diesel fuel in fully-immersed, mobile and stationary applications. Engineered for fully submersible use, these hoses are excellent for use on gas tank fuel pumps.



- Comprised of a FKM tube and cover with synthetic fiber reinforcement.
- Working Pressure: up to 100 psi.
- Exceeds required SAE 30R10 standard.
- Temperature Range: -40°F to +302°F (-40°C to +150°C).
- Product Type: 4219

Part No. 1 ft.	Part No. 10 ft.	Part No. 32.8 ft.	I.D. (in.)
27086	27087	27089	¼
27093	27080	27083	5/16
27097	27081	27084	3/8

## FUEL CAPS

Rugged, heavy-duty construction. Meet or exceed OEM specifications. Caps fit both shallow and deep cam filler necks - vented, non-vented and vented anti-surge. Three configurations available for most popular applications. Product Type: 7410

⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)



### Locking Fuel Caps

- Comes with two keys.



### Exterior Fuel Caps

- Attractive chrome-plated finish.



## HEAVY-DUTY SADDLE TANK CAPS

Heavy metal construction throughout. Meets I.C.C. requirements.

- Available for side or saddle tanks.
- Locking caps come with two keys.

⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)







TRANSMISSION OIL COOLER HOSE

Gates Transmission Oil Cooler Hose is engineered with synthetic rubber tube, and an oil and abrasion resistant black hypalon cover, to provide a safe, heat, ozone, and chemical-resistant connecting line between the oil cooler and transmission. The cooler hose is reinforced with a braided cord for increased strength.



- Easy-to-follow instructions and hose diameter indicator in each package.
- Nitrile tube and CSM cover.
- Synthetic Fiber Reinforcement.
- Meets or exceeds SAE 100R6.
- Working Pressure: 400 psi.
- Temperature Range: -40°F to +275°F (-40°C to +°C) constant and -40°F to +300°F (-40°C to +150°C) intermittent.
- Product Type: 3289 and 3319

Part No. 3 ft.	Part No. 25 ft.	Part No. 50 ft.	I.D. (in.)	Press. Burst
27056	27058	27060	5/16	1600
27057	27059	27061	3/8	1600
27065	27066	27067	1/2	1600

OIL FILLER CAPS

Gates Oil Caps are top quality, constructed of impact resistant plastic and heavy-gauge metal to assure long service life.



- Wide range of application covering all makes and models.
- Manufactured to meet or exceed OEM specifications in function, form & fit.
- Special finish resists rust and provides excellent protection against underhood heat.
- Product Type: 7410

⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)

**BULK POWER STEERING HOSE**

Allows “custom fit” cutting and assembly for low pressure fluid return lines.




- Use with return line end fittings if required.
- Meets SAE J189 requirements.
- Temperature Range: -40°F to +275°F (-40°C to +135°C) (+300°F (149°C) for CPE hose).
- Product Type: 3283 and 7741

Part No.	I.D. (in.)	Length (ft.)	Description
362860	1 <sup>1</sup> / <sub>32</sub>	1	SAE J189 Return Hose
362870	1 <sup>1</sup> / <sub>32</sub>	2	SAE J189 Return Hose
362880	1 <sup>1</sup> / <sub>32</sub>	3	SAE J189 Return Hose
349960	1 <sup>1</sup> / <sub>32</sub>	25	SAE J189 Return Hose
361960	3 <sup>3</sup> / <sub>8</sub>	2	SAE J189 Return Hose
361970	3 <sup>3</sup> / <sub>8</sub>	3	SAE J189 Return Hose
350020	3 <sup>3</sup> / <sub>8</sub>	4	SAE J189 Return Hose
362190	3 <sup>3</sup> / <sub>8</sub>	4	C.P.E. Return Hose (Chlorinated Polyethylene)
349950	3 <sup>3</sup> / <sub>8</sub>	25	C.P.E. Return Hose (Chlorinated Polyethylene)
350010	3 <sup>3</sup> / <sub>8</sub>	25	SAE J189 Return Hose
362090	1 <sup>1</sup> / <sub>2</sub>	3	Suction Hose
349970	1 <sup>1</sup> / <sub>2</sub>	10	Suction Hose
362200	5 <sup>5</sup> / <sub>8</sub>	3	SAE J189 Return Hose
350030	5 <sup>5</sup> / <sub>8</sub>	3 1 <sup>1</sup> / <sub>2</sub>	Suction Hose
349980	5 <sup>5</sup> / <sub>8</sub>	10	Suction Hose
362100	3 <sup>3</sup> / <sub>4</sub>	3	Suction Hose
349990	3 <sup>3</sup> / <sub>4</sub>	10	Suction Hose



**POWER BRAKE VACUUM HOSE**

Light-duty hose specially engineered for power brake applications on passenger cars and light trucks.

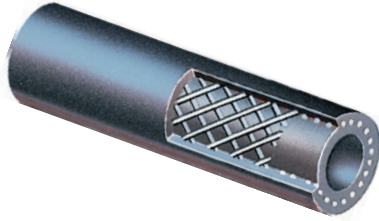


- Ozone-resistant EPDM cover.
- Textile reinforcement.
- Vacuum rating 30 in. Hg.
- Working Pressure: 85 psi.
- Meets SAE 1403 Type L.
- Complies with DOT FMVSS 106VL.
- Temperature Range: -40°F to +257°F (-40°C to +125°C).
- Product Type: 3276

Part No. 3 ft.	Part No. 50 ft.	I.D. (in.)
27232	27230	1 <sup>1</sup> / <sub>32</sub>
27233	27231	1 <sup>5</sup> / <sub>32</sub>

**GREEN STRIPE® VACUUM BRAKE HOSE**

Green Stripe® Vacuum Brake Hose provides an extra heavy-duty hose solution designed to fit most air brake systems on trucks, trailers, and heavy equipment. These hoses resist collapsing or deforming even under high vacuum at elevated temperatures.

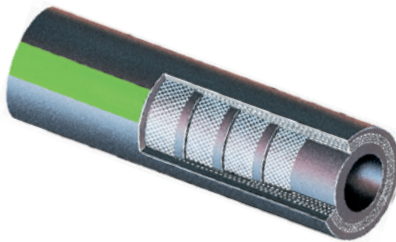


- Rubber-infused fabric construction provides superior strength.
- Oil-resistant neoprene construction.
- Standard air brake coupling compatible.
- Rated at 30 in. Hg.
- Working Pressure: 85 psi.
- Exceeds SAE J1403, Type H requirements.
- Complies with DOT FMVSS 106VH requirements.
- Temperature Range: -40°F to +257°F (-40°C to +125°C).

Part No. 50 ft.	I.D. (in.)	Min. Burst Press. (psi)
27212	5/8	800
27213	3/4	800

**HEAVY-DUTY GREEN STRIPE® AIR BRAKE HOSE**

Air Brake Hose for Truck and Bus, tractor trailer and other moving equipment. Can be used as flexible connector between frame and axle.

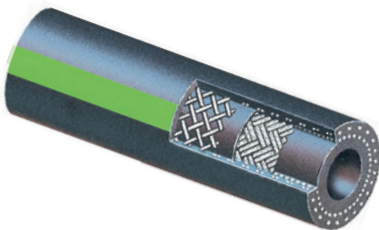

- Compatible with standard air brake couplings.
- Neoprene construction is oil resistant.
- Two-braid rayon reinforced construction with smooth cover.
- Working Pressure: 225 psi.
- Meets SAE J1402 Type A.
- Complies with DOT FMVSS 106.
- Temperature Range: -40°F to +100°F (-40°C to +212°C).
- Product Type: 3245E

**Note:** Federal law requires registration with the Department of Transportation for anyone producing air brake hose assemblies with swaged or crimped fittings.

Part No. 50 ft.	Part No. 250 ft.	I.D. (in.)	Min. Burst Press. (psi)
27220	28304	3/8	800
27221	—	1/2	800

### POLARSEAL® HOSE

PolarSeal® Hose is designed for environmentally-safe liquid and gaseous LR134a and R12 refrigerant applications in automotive air conditioning and industrial systems, including tractors, construction trucks, mobile and stationary refrigeration units. Designed to minimize permeation of R134a and R12 refrigerant.



- Cover is black synthetic EPDM rubber.
- Nylon barrier inside black chloroprene rubber tube is reinforced with spiraled polyester.
- Meets or exceeds SAE J2064 Type C, Class II.
- Temperature Range: -22°F to +257°F (-30°C to +125°C), Class II.

**Note:** For a complete listing of PolarSeal Hose and Couplings, see Gates Hydraulic Catalog 431-2080.

### POLARSEAL® II HOSE

The PolarSeal® II Hose was developed as part of the PolarSeal II series and performs best when paired with PolarSeal II couplings and clamps. The elastomeric tube has fabric reinforcement for improved durability, and the cover is heat, moisture, and ozone resistant. This hose is recommended for use on school and transit busses, RVs, limos, and other heavy equipment vehicles that run long AC lines or AC lines that are difficult to service.



- Cover is heat, moisture and ozone resistant.
- Elastomeric tube with fabric braid reinforcement.
- Meets SAE J2064 Type C, Class I - use with R12, R13A and R22 refrigerants.
- Temperature Range: -22°F to +257°F (-30°C to +125°C).

**Note:** For a complete listing of PolarSeal II Hose and Couplings, see Gates Hydraulic Catalog 431-2080.

### POLARSEAL® AND POLARSEAL® II COUPLINGS AND ACCESSORIES

Systems perform better when using parts that were designed and manufactured to work together. If you use Gates PolarSeal® Air Conditioning Hoses for your applications, use Gates PolarSeal AC Couplings to complete your assembly. These hose and couplings were designed for a guaranteed, long-lasting fit to give you the best, most reliable performance.




- 75 coupling families ensure the right connection.
- Available in straight, 45°, and 90° styles.
- 4 Sizes of O-Rings specially compounded for R134A refrigerants also available.

**Note:** For a complete listing of PolarSeal Couplings, see Gates Hydraulic Catalog 431-2080.



## WINDSHIELD WASHER AND VACUUM SYSTEM

### WINDSHIELD WASHER AND VACUUM TUBING (NON-REINFORCED)

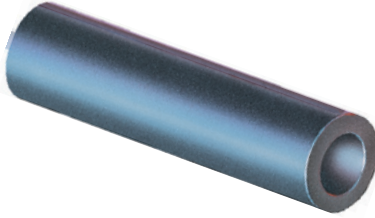


The ideal hose to replace the PVC tubing used for windshield or headlight washers in cars, to connect vacuum-operated car accessories and to discharge radiator overflow or rainwater.

- Vacuum and kink resistant construction.
- Vacuum rated to 24 in. Hg (610mm).
- Meets SAE J1037, J942b specifications.
- Working Pressure: 25 psi.
- Temperature Range: -40°F to +257°F (-40°C to +125°C).
- Product Type: 4040

**\*Gates also offers packaged windshield washer and vacuum tubing (non-reinforced) hose in convenient, six foot lengths of hose in self-service, reusable, recyclable package. Can be displayed on pegboard.**

Part No. 6 ft.*	Part No. 25 ft.	Part No. 50 ft.	Part No. 250 ft.	I.D. (in.)	Nipple Size (in.)
27037	—	27041	—	7/64	1/8
27038	—	27042	27035	5/32	3/16
27039	—	27043	27036	7/32	1/4
27040	—	27044	—	1/4	5/16
—	27050	—	—	5/16	3/8
—	27053	—	—	3/8	7/16

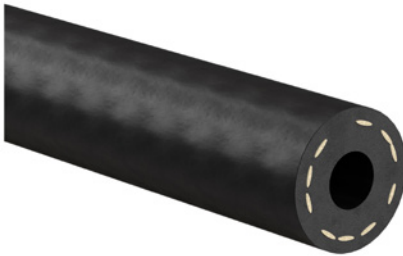


### WINDSHIELD WIPER AND VACUUM HOSE (REINFORCED)

Ideal for windshield washers, vacuum-operated accessories and radiator overflow applications. Reinforced construction for pressure applications.

- Kink and collapse resistant.
- EPDM tube and cover resists splitting or cracking during stem insertion.
- Working Pressure: 50 psi.
- Temperature Range: -40°F to +257°F (-40°C to 125°C) to 26 in. Hg.
- Product Type: 4251

Part No. 50 ft.	I.D. (in.)	Nipple Size (in.)
27072	5/32	3/16
27073	7/32	1/4
27074	1/4	5/16



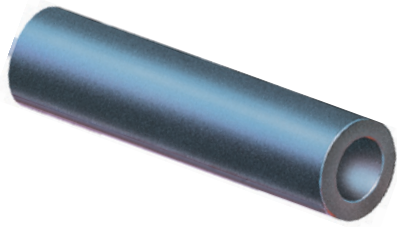

**RADIATOR OVERFLOW VACUUM TUBING**

Economical rubber tubing for radiator overflow, engine vacuum lines, and windshield washer fluid lines.

- Weather resistant EPDM tube without reinforcement.
- Use on hose bead fitting with or without hose clamps.
- Self-service packaging that can be displayed on pegboard.
- Meets SAE J1037, SAE 942, SAE J200 M4CA710 A25 B35 C32 EA14 F19.
- Temperature: -40°C to +125°C (-40°F to +257°F).
- Product Type: 4040

Part No. 3 ft.	I.D. (In.)	Nipple Size (in.)
27555	3/16	3/8
27556	3/8	7/16



**WET ARM WIPER TUBING**


One size, small outside diameter washer tubing designed as an integral part of windshield wiper systems.

- Same construction as windshield washer and vacuum tubing.
- Meets SAE J1037, J942b specifications.
- Product Type: 4040

Part No. 6 ft.	Part No. 50 ft.	I.D. (in.)	Nipple Size (in.)
27030	27045	3/32	1/16



**TURBOCHARGER HOSE**

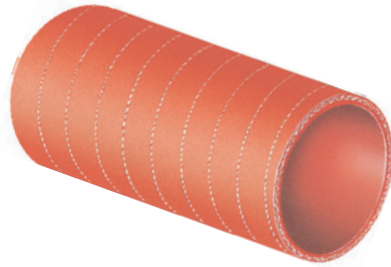

Gates Turbocharger Hoses are specially compounded for use as a short, flexible connector between the air intake and the turbocharger. Can also be used for turbocharger air discharge.

- Highly visible orange color helps distinguish this hose from engine coolant hose.
- Silicone elastomer inner liner reinforced with woven fiberglass fabric and coated with orange silicone rubber.
- Resists coolants, weathering and ozone.
- Resists high temperatures and pressures.
- Product Type: 7734

Part No.	I.D. (in.)	Length (ft.)	Work. Press. (psi)
26116	1	36	45
26124	1½	36	40
26128	1¾	36	35
26132	2	36	35
26136	2¼	36	30
26138	2⅝	36	30
26140	2½	36	30
26142	2⅞	36	15

Part No.	I.D. (in.)	Length (ft.)	Work. Press. (psi)
26144	2¾	36	25
26001	3	3	25
26148	3	36	25
26002	3⅜	3½	15
26003	3⅝	6	15
26154	3⅝	36	15
26004	3½	3	30

Part No.	I.D. (in.)	Length (ft.)	Work. Press. (psi)
26156	3½	36	20
26160	3¾	36	15
26162	3⅞	36	15
26164	4	36	15
26166	4½	36	15
26007	5	3½	15
26008	5½	3½	15

**GREEN STRIPE® RING RETAINED TURBOCHARGER HOSE**



Made for turbocharged Class 8 and heavy-duty diesel engines. Multi-hump design isolates vibration and absorbs rotational shock. Depending on application, hose is engineered with three or four rings to maintain design integrity.

- Four layer silicone construction with aramid fiber reinforcement for maximum durability.
- Meets or exceeds OEM specifications.
- Working Pressure: 25 psi.
- Temperature Range: -60°F to +500°F (-51°C to +260°C).
- Product Type: 4177

Part No. 6 in.	Part No. 8 in.	I.D. (in.)
26200	—	3
26201	—	3½
26203	26204	4



**AIR VENT HOSE**



Extremely flexible light-duty hose for air cleaner-to-engine connections, defroster ducts and air or heater ducting.

- Reinforcement: Fabric ply and double steel wire.
- Easy to cut to size with knife and wire cutters.
- Helical wire construction.
- Heat and oil resistant tube.
- Temperature Range: -40°F to +212°F (-40°C to +100°C).
- Product Type: 4663

**Note:** For abrasive environments use Gates Green Stripe® Heavy-Duty Air Vent Hose.

**Caution:** Not recommended for conveying liquids.

Part No. 10 ft.	I.D. (in.)	Work. Press. (psi)	Vacuum Rating (in. Hg.)
24300	5/8	10	5
24301	3/4	10	5
24302	7/8	10	5
24303	1	10	5
24304	1 1/4	10	5
24305	1 3/8	10	5
24306	1 1/2	10	5
24307	1 5/8	10	5
24308	1 3/4	10	5
24309	1 7/8	10	5
24310	2	5	3
24311	2 1/8	5	3

Part No. 10 ft.	I.D. (in.)	Work. Press. (psi)	Vacuum Rating (in. Hg.)
24312	2 1/4	5	3
24313	2 3/8	5	3
24314	2 1/2	5	3
24315	2 5/8	5	3
24316	2 3/4	5	3
24317	3	5	3
24318	3 1/2	5	3
24319	3 3/8	5	3
24320	4	5	3
24321	4 1/2	5	3
24322	5	5	3
24323	5 1/2	5	3

**GREEN STRIPE® HEAVY-DUTY AIR VENT HOSE**



Specifically designed for air cleaner-to-engine connections and other ducting applications.

- Smooth interior offers minimum air resistance for maximum efficiency.
- Flexible, helical wire reinforced.
- Easy to cut to size with knife and wire cutters.
- Cover is heat, oil and abrasion resistant.
- Heat and oil-resistant tube.
- Working Pressure: 10 psi.
- Temperature Range: -40°F to +257°F (-40°C to +125°C).
- Product Type: 4663

**Caution:** Not recommended for conveying liquids.

Part No. 10 ft.	I.D. (in.)	Vacuum Rating (in. Hg.)
24324	4	7
24325	4 1/2	7
24326	5	6
24327	5 1/2	6



**AV SERIES AIR VENT HOSE**

Specifically designed for air cleaner-to-engine connections and other ducting applications.

- Available in pre-formed Hump, Straight and Curved configurations.
- Heat and oil resistant.
- Temperature Range: -40°F to +225°F



Style	Part No.	(I.D. x Length) (in.)
Hump	23002	4 x 5
	23004	5 x 6
	23005	5 ½ x 6
	23006	6 x 5
Reducer	23100	3 ½ x 3 x 5 ¼
Hump	23101	4 x 3 x 5 ¼
	23106	6 x 5 ½ x 6
	23107	7 x 6 x 5
Straight	23400	4 x 22
Flexible	23401	6 x 19
	23402	6 ⅞ x 19


Style	Part No.	(I.D. x Length) (in.)
Molded	23201*	3 x 5 ¼ x 90°
Elbow	23202	3 ½ x 5 ½ x 45°
	23203*	3 ½ x 5 ½ x 90°
	23208	5 x 5 ¼ x 45°
	23209	5 x 6 x 90°
	23215 *	6 x 6 ½ x 45°
	23216 *	6 x 7 ½ x 45°
	23218 *	6 x 7 x 90°
Reducer Elbow	23221	7 x 7 ½ x 90°
	23300*	6 x 5 ½ x 90°

\*Ribbed



**SAFETY STRIPE® AIR HOSE**

Safety Stripe® Air Hose provides a durable, premium hose, available in 25 or 50-foot lengths, for garage and service station air impact tools.

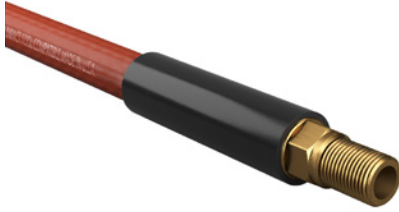

- Bend restrictors for extended life.
- Factory assembled male couplings with 300 lb. minimum coupling pull.
- High flexibility is easy on wrists.
- High strength reinforcement.
- Perforated EPDM red cover that resists ozone and abrasion.
- Working Pressure: 300 psi.
- Temperature Range: -40°F to +200°F (-40°C to +93°C).
- Product Type: 3215

Part No. 25 ft.*	Part No. 50 ft.*	I.D. (in.)	Coupling Thread Size
27485	27486	1/4	1/4 - 18NPT
27488	27489	3/8	1/4 - 18NPT
27491	27492	1/2	1/2 - 14NPT

\*⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)

**CHARTER® AIR HOSE**

Designed for multi-purpose air hose applications. Capable of impact tool use.



- Factory applied male couplings have 250 lb. minimum coupling pull.
- Perforated EPDM red cover is ozone and abrasion resistant.
- Textile reinforcement.
- Working Pressure: 200 psi.
- Temperature Range: -40°F to +200°F (-40°C to +93°C).
- Product Type: 3215

Part No. 25 ft.*	Part No. 50 ft.*	Part No. 300 ft.**	I.D. (in.)	Coupling Thread Size
27475	27476	28673	1/4	1/4 - 18NPT
27478	—	28674	3/8	1/4 - 18NPT
—	27479	—	3/8	1/4 - 14NPT

\*⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)

\*\*300' lengths are not coupled.





**HYBRID AIR HOSE**

Gates hybrid polymer air hose combines flexibility and strength together, making it the best hose for air service applications.



- Easy coiling after use.
- High abrasion and chemical resistance.
- Kink-resistant, even under pressure
- Lightweight, extremely flexible construction.
- Superior bend radius.
- Zero memory, allowing it to lay-flat.
- Working Pressure: 300 psi.
- Fittings and ferrules are 100% brass and both ends have heavy-duty PVC bend restrictors.
- Product Type: 7746

Part No.*	I.D. (in.)	Length (ft.)	Coupling Thread Size
27568	¼	25	¼ NPT Male, ¼ NPT Male
27569	¼	50	¼ NPT Male, ¼ NPT Male
27570	⅜	25	¼ NPT Male, ¼ NPT Male
27571	⅜	50	¼ NPT Male, ¼ NPT Male
27580	⅜	2	¼ Male Ball Swivel, ¼ NPT Female
27582	⅜	4	¼ Male Ball Swivel, ¼ NPT Female
27583	⅜	6	¼ Male Ball Swivel, ¼ NPT Female
27572	½	25	½ NPT Male, ½ NPT Male
27573	½	50	½ NPT Male, ½ NPT Male

\*⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)

**BULK HOSE:**

Bulk premium Hybrid Air Hose to create the custom length hose needed for any job.

Part No.	I.D. (in.)	Length (ft.)
27586	¼	250
27584	⅜	250
27585	½	165

**FITTING:**



- Air hose fittings for creating customized hybrid air hose lengths or repair existing damaged fittings.
- Solid brass for corrosion resistance.
- Spiral bend restrictor to increase hose durability.
- Easy installation and removal.
- Product Type: 7008

Part No.*	Size	Description
91071	¼ MNPT x ⅜ Barb Size	End Fitting
91073	½ MNPT x ½ Barb Size	End Fitting
91072	⅜ x ⅜ Barb Size	Splicer

\*⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)



**REEL:**

Multi-functional retractable air hose reel for all your shop's needs.

- Fully enclosed automatic reel stops or rewinds the hose at any point.
- Gradual return feature to control rewind if the hose is accidentally released.
- Automatic guide allows hose to rewind in systematic manner.
- Product Type: 7746

Heavy-Duty steel air hose reel for indoor or outdoor use.

- Steel construction w/ dual supporting arms for sturdiness.
- Galvanized and powder coated for durability.
- Multi-position release ratchet.
- Product Type: 7008

Part No.*	I.D. (in.)	Length (ft.)	Description
91068	3/8	50	Multi-functional Retractable Air Hose Reel
91069	3/8	50	Heavy-Duty Steel Air Hose Reel
91070	1/2	50	Heavy-Duty Steel Air Hose Reel

\*⚠ WARNING: Cancer and Reproductive Harm – [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)

**HOSE STOP:**

Hybrid Air Hose Stops are utilized on hybrid air hose to keep the entire hose from entering air hose reels when rewinding.

- High density polyethylene for long life.
- Adjustable to retain the preferred length of hose outside reel.
- Rubber friction pad for excellent grip on hose.
- Product Type: 7008




Part No.	I.D. (in.)	Fits Hose Size (in.)
91074	1/2	3/8
91076	5/8	1/2

**CHARTER® MULTI-USE AIR/WATER HOSE**

Ideal for air and water applications. Engineered for heat, abrasion and ozone resistance.

- EPDM rubber tube and cover.
- Two layers of spiral synthetic reinforcement.
- Gates Power Crimp® specifications available\*
- Working Pressure: 200 psi.
- Temperature Range: -40°F to +200°F (-40°C to +93°C).
- Product Type: 3204

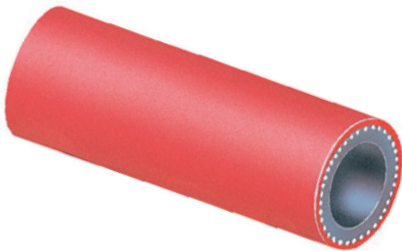

\*Contact your local Gates sales associate for specification information.


**Caution:** Do not use for oil, grease or fuel transfer.

Part No. 50 ft.	Part No. Reel	Reel Length (ft.)	I.D. (in.)
28823	28800	600	1/4
28825	28803	600	5/16
28826	28806	600	3/8
28828	28809	600	1/2
28830	28812	550	5/8
28832	28815	500	3/4
28836	28818	350	1



**MULTI-USE HOSE**

For handling lower pressure air, water, agricultural spraying, oil or grease. Can also be used for air spray painting.

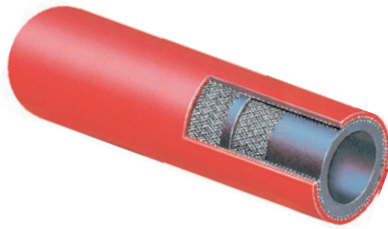

- Nitrile tube and cover provide high oil resistance.
- One braid polyester cord reinforcement.
- Working Pressure: 315 psi.
- Temperature Range: 0°F to +212°F (-18°C to +100°C).
- Product Type: 3223

**Caution:** Not recommended for use as small I.D. by-pass, coolant and heater hose. Do not use for fuel transfer applications.

Part No. 50 ft.	Part No. 300 ft.	I.D. (in.)
27402	28652	1/4
27404	28657	5/16
27406	28661	3/8
27410	28665	1/2
27414	28667	5/8
27418	28671	3/4
27420	28765	1

**HYBRID WATER HOSE**

Gates innovative Water Hose featuring premium hybrid polymer material for extreme flexibility.



- Easy coiling after use.
- High abrasion and chemical resistance.
- Kink-resistant, even under pressure.
- Superior bend radius.
- Zero memory, allowing it to lay-flat.
- Working Pressure: 150 psi.
- Fittings are plated with heavy-duty nickel and have spring guard.
- Product Type: 7746


Part No. 50 ft.	Part No. 75 ft.	I.D. (in.)	Coupling Thread Size
27574	27575	5/8	11 1/2 - 3/4 GHT
27577	—	3/4	11 1/2 - 3/4 GHT

## EXHAUST SYSTEM HOSE



### EXHAUST HOSE (HARDWALL) WIRE REINFORCED

Heavy-duty fabric-reinforced hose with a helical steel wire reinforcement to meet marine water and wet exhaust hose requirements.

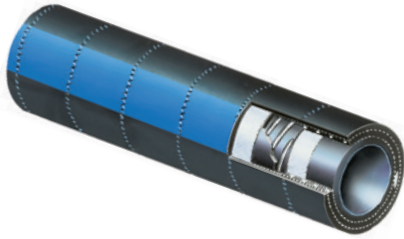

- Features blue layline for easy identification.
- Resists heat and oil.
- Meets SAE J2006 requirements.
- Working Pressure: 100 psi for water application, 10 psi for exhaust application.
- May be used for engine water circulation, discharge lines, heat exchangers and wet exhaust connections.
- Product Type: 4686

Part No. 12.5 ft.	I.D. (in.)
250-1184	1 1/8
250-1144	1 1/4
250-1384	1 3/8
250-1124	1 1/2
250-1584	1 5/8
250-1344	1 3/4
250-1784	1 7/8
250-2004	2

Part No. 12.5 ft.	I.D. (in.)
250-2184	2 1/8
250-2144	2 1/4
250-2384	2 3/8
250-2124	2 1/2
250-2584	2 5/8
250-2344	2 3/4
250-2784	2 7/8
250-3004	3

Part No. 12.5 ft.	I.D. (in.)
250-3124	3 1/2
250-4004	4
250-4124	4 1/2
250-5004	5
250-5124	5 1/2
250-6004	6



**POWERATED® "70" BELT MERCHANDISER**

In-store merchandiser used to display Gates PowerRated® belts. Merchandiser alone includes belt length finder, catalog and racks to hang belts on. Merchandiser plus assortment includes belt length finder, catalog, number tags and top 70 selling PowerRated belts.

- Designed to professionally and cleanly display the Gates PowerRated line of belts.
- Merchandiser with assortment takes the guessing out of which belts to stock by providing the Gates recommended assortment.
- Six four feet metal racks.
- Part No. 91230 and Part No. 91234 - display only.

**Note:** Pegboard and gondola not included.

**BARRICADE® FUEL LINE AND VACUUM TUBING MERCHANDISER/ ASSORTMENT**



Attractive, metal cabinet comes assembled. Holds and dispenses 12 reels of fast-selling Gates Barricade® Fuel Line, EEC and PCV hoses, or tubing for windshield washers and vacuum-operated accessories.

- Contains 12 fast-selling hose sizes on individually mounted and replaceable reels.
- Handy measuring scale printed on lid makes it easy to measure exact size of hose needed.
- Can be displayed on counter or mounted on wall.
- Attached chain designed to hold hand-held hose cutter.
- Base dimensions are 16"D x 19 1/2"W x 18"H.
- Part No. 91184 and Part No. 91183 – display only.

**Note:** Combine this merchandiser with the Heater Hose Merchandiser to create the modular Hose Center.

Fuel Line/PPVC/EEC Hose 25 ft.		Vacuum Tubing 50 ft.		Baricade® Carburetion Hose 25 ft.		Baricade® Injection Hose 25 ft.	
Part No.	I.D. (in.)	Part No.	I.D. (in.)	Part No.	I.D. (in.)	Part No.	I.D. (in.)
27000	1/8	27041	1/8	27313	1/4	27339	1/4
27000	3/16	27042	5/32	27314	5/16	27340	5/16
		27043	7/32	27315	3/8	27341	3/8
		27044	1/4				

**HEATER HOSE MERCHANDISER**



Attractive, yet rugged metal cabinet organizes and keeps stock neat. Designed to hold dispensing cartons, making it easy to pull hose out for measuring. Create a "Hose Center" by adding the popular Gates Fuel Line/PCV/EEC and Vacuum Tubing Merchandiser to the top of this unit.

- Holds one each 50 ft. cartons of 1/2", 5/8" and 3/4" heater hose.
- Handy 36" measuring scale printed on side makes it easy to measure the exact length of hose needed.
- Assembled unit measures 19 11/16"W x 16"D x 40"H.
- Part No. 91160

**Note:** Merchandiser does not include hose.





### HOSE REEL MERCHANDISER

Trouble-free six reel metal merchandiser for hose.

- Holds six small reels of fuel, vacuum, coolant, as well as other hose.
- Dimensions are 16"W x 31"H.
- Part No. 91127



### HEATER HOSE CONNECTOR ASSORTMENT

Sturdy impact-resistant plastic case holds an assortment of 36 hose connectors for 1/4" through 3/4" I.D. hose.

- Case opens from either side.
- Handy plan-o-gram inside both lids identifies location of each type and size connector.
- Assortment contains two each elbow, straight, and "T" connectors.
- Provides convenient storage for complete line of connectors.
- See page A18 for individual connector part numbers.
- Part No. 91175

Part No.	O.D. (in.)	O.D. Description
28600	5/16	Straight Connector
28602	3/8	Straight Connector
28603	1/2	Straight Connector
28604	5/8	Straight Connector
28605	3/4	Straight Connector
28606	1	Straight Connector
28620	5/16	Elbow Connector
28622	3/8	Elbow Connector
28623	1/2	Elbow Connector

Part No.	O.D. (in.)	O.D. Description
28624	5/8	Elbow Connector
28625	3/4	Elbow Connector
28626	1	Elbow Connector
28630	5/16	Tee Connector
28632	3/8	Tee Connector
28633	1/2	Tee Connector
28634	5/8	Tee Connector
28635	3/4	Tee Connector
28638	1	Tee Connector



**FUEL HOSE CONNECTOR ASSORTMENT**

Upgraded component range to match Gates heater hose offerings.

- Inside cover plan-o-gram easily identifies the location of each type and size connector.
- Premium storage container can be connected to create a double-sided unit.
- See page A18 for individual connector part numbers.
- Part No. 91174

Part No.	O.D. (in.)	Description
28561	3/32	Straight Connector
28562	1/8	Straight Connector
28563	5/32	Straight Connector
28564	3/16	Straight Connector
28601	1/4	Straight Connector
28600	5/16	Straight Connector
28602	3/8	Straight Connector
28603	1/2	Straight Connector
28571	3/32	Elbow Connector
28572	1/8	Elbow Connector
28573	5/32	Elbow Connector
28574	3/16	Elbow Connector

Part No.	O.D. (in.)	Description
28621	1/4	Elbow Connector
28620	5/16	Elbow Connector
28622	3/8	Elbow Connector
28623	1/2	Elbow Connector
28581	3/32	Tee Connector
28582	1/8	Tee Connector
28583	5/32	Tee Connector
28584	3/16	Tee Connector
28631	1/4	Tee Connector
28630	5/16	Tee Connector
28632	3/8	Tee Connector
28633	1/2	Tee Connector

**REDUCER CONNECTOR ASSORTMENT**

Upgraded component range to match Gates fuel line and heater hose offerings.

- Inside cover plan-o-gram easily identifies the location of each type and size connector.
- Premium storage container can be connected to create a double-sided unit.
- See page A18 for individual connector part numbers.
- Part No. 91177



**REDUCER CONNECTORS**

Part No.	O.D. (in.)
28591	3/32 to 1/8
28592	1/8 to 5/32
28593	3/16 to 1/4
28594	5/16 to 3/8
28609	3/8 to 1/2
28610	1/2 to 5/8
28611	5/8 to 3/4
28612	1 to 3/4
28639	5/16 to 1/2
28640	3/8 to 3/4

**TEE REDUCER CONNECTORS**

Part No.	End 1 O.D. (in.)	90° Tee O.D. (in.)	End 2 O.D. (in.)
28636	5/8	3/8	5/8
28637	3/4	3/8	3/4
28641	5/8	3/8	5/8
28642	1/2	1/4	1/2

**"Y" CONNECTORS**

Part No.	O.D. (in.)
28551	3/32
28552	1/8
28554	3/16



### FUEL CAP CABINET

Attractive display keeps fuel caps neatly organized. The cabinet is attractive and eye-catching, as well as rugged and durable. There is room to add part numbers beyond the basic 80 percent coverage, whether new numbers or for a specific need. Sturdy steel construction for prolonged life and durability. Part No. 91117



### HOSE HANGERS

Convenient plastic hook hangers that can quickly be attached and detached from individual hoses for storage and/or display.

- 50 per package.
- Will not damage hose.
- Works well with Gates belt boards Part No. 91488.
- Part No. 91999



### SERPENTINE RATCHETING WRENCH SET

Provides fast way of releasing tension on serpentine belt drives. Reversible, 21-tooth ratcheting heads on each end allow for better tool positioning and more swing than standard serpentine belt wrenches.

- Wrenches are 21 1/2" long, 6" longer than competitive designs for increased leverage.
- Includes eight sizes for maximum application coverage: 13mm, 14mm, 15mm, 16mm, 17mm, 3/8", 1/2" and 3/4."
- Part No. 91011.



### PRODUCT GRABBER (TELESCOPING POLE)

Allows easy product hanging and retrieval from belt boards that are installed high on walls.


- 4' pole, extends to 11'.
- Extra-long 8" hook for extended reaches.
- Part No. 91233.



### V-RIBBED AND V-BELT BELT LENGTH FINDER

Gates Micro-V and V-Belt Length Finder provides the ability to quickly and accurately measure almost any Micro-V or V-Belt. Featuring an intuitive and robust dual-sided design, the tool is capable of measuring Automotive Micro-V belts up to 120", and Automotive, Lawn & Garden, and Truck & Bus V-Belts up to 120".

- Measurements for the Micro-V side include inches as well as millimeters.
- Part No. 91219.

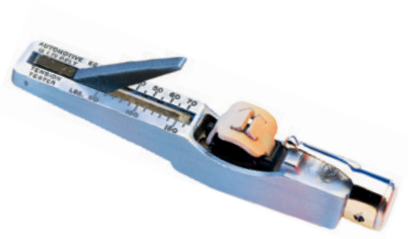


**KRIKIT V-BELT TENSION GAUGE**

This easy-to-use gauge is designed for tensioning all automotive V-belts up to, and including, 7/8" top widths.

- Scale reads in pounds and kilograms. Measures tension from 30 to 160 lb., and 15 to 75 kg.
- Die-cast aluminum body, nylon indicator arm and pressure pad.
- Fits in pocket with stainless steel pocket clip.
- Part No. 91107.

**Note:** Not for use on timing belts.

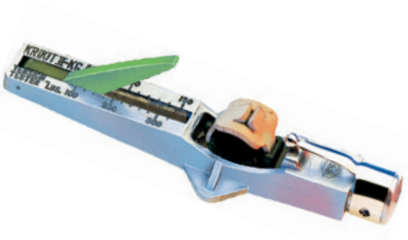

**KRIKIT II V-RIBBED BELT TENSION GAUGE**

Designed for tensioning V-ribbed belts on passenger cars, light trucks, heavy trucks and buses.

- Bright green pressure pad and indicator arm.
- Calibrated to measure tension from 100 to 320 lb., and 50 to 150 kg.
- Measure belts up to eight ribs in width.
- Part No. 91132.

**Note:** Not for use on timing belts.



**COOLANT AND BATTERY REFRACTOMETER**

Measures concentration of coolant mixture in engine. Place small sample of coolant on lens, then hold lens up to light source. Light bends through liquid, providing an accurate reading on scale.

- Measuring coolant concentrations is essential to cooling system maintenance.
- Most technicians use hydrometers to test coolant concentration via gravity or floating ball scales.
- Hydrometers must be temperature corrected, and may give false readings when testing new, propylene-based coolants.
- Gates refractometer automatically corrects for temperature on both types of coolant (ethylene and propylene glycol) while measuring battery charge levels.
- Part No. 91001.



**HOSE CLAMP PLIERS SET**

Quickly and easily reach, install, release, or even remove hard-to-reach hose clamps with this handy kit.

- Set includes: Remote action flexible hose clip tool with 600mm reach, large flat-band pliers (angled for access), and hose release hook.
- Part No. 91067.





**HOSE CUTTERS (HAND-HELD) AND REPLACEMENT BLADES**

Makes clean cuts with no ragged edges. Cuts most non-metal reinforced rubber hose. Excellent for cutting textile-reinforced hose.

Features Advantages:

- Blade closes into handle for safety.
- Cutter and blades packaged individually on shrink-wrapped cards.
- Lightweight with nylon handles.

Part No.	Description	Cuts to Hose I.D.
91143	Large I.D. Hose Cutter	3"
91153	Small I.D. Hose Cutter	1 1/2"
91144	Large I.D. Hose Cutter Replacement Blade	—
91154	Small I.D. Hose Cutter Replacement Blade	—

**POWERCLEAN™ FLUSH TOOL**



Using clean water and compressed air, the PowerClean Flush Tool "water hammers" accumulated sludge and scale deposits without the use of harsh chemicals or solvents. It cleans radiators, heat exchangers, hoses and engine blocks more effectively than conventional flushes, maintains system integrity and ensures warranty coverage on replacement parts, including water pumps.

- The Gates PowerClean Flush Tool patented process uses fixed dimensional control of the air and liquid flow paths.
- The process allows air to pressurize the cleaning fluid to scrub deep into corners and crevices, eliminating trapped debris.
- While the "pulse" is intensified with some limited backpressure, the pressure is immediately regulated to a safe level if a hard blockage exists eliminating the possibility of heater core damage from excessive system pressure.
- Water line backflow preventer.
- Large rubber tip for radiator necks and direct flushing of the engine block.
- Small rubber tip on whip hose for direct access to heater core tube stubs.
- 5/8" And 3/4" heater hose barbs for flushing heater cores or engine blocks.
- Part No. 91002\*.

Part No.	Description
91002-1	Storage Case with Foam Inserts
91002-2*	Patented Flushing Gun
91002-3*	Small Tip for Heater Core
91002-4*	Large Tip for Radiators
91002-5*	5/8" Heater Hose Connector

Part No.	Description
91002-6*	3/4" Heater Hose Connector
91002-7*	Whip Hose W/Quick Couplers
91002-8*	Supply Hose Backflow Preventer
91002-9	4 1/2" Large Tip for Trucks

\*⚠ WARNING: Cancer and Reproductive Harm – www.P65Warnings.ca.gov

### POLARSEAL® II PLIERS

PolarSeal II Pliers are used to crimp clamps on PolarSeal II couplings. Any one of three pliers will get the job done. Each tool is designed with slightly different features.



#### Ratcheting Plier – Part No. 77953

- The ratcheting plier features a no-release function. Once a crimp is started the plier does not release until the crimp is complete. This guarantees a proper seal, with no guess work in the crimp.



#### Straight Jaw Plier – Part No. 77952

- The straight jaw plier is a low cost, no-frills plier. This plier works best when there are no obstructions to hinder gripping the clamp or completing the crimp.



#### Notched Jaw Plier – Part No. 77951

- The notched jaw plier is designed for the hard-to-reach places. If obstructions prohibit the use of straight jaw pliers this is the tool to use. Use either side or the front of this plier to make the crimp.



# ABBREVIATIONS



A. Amperes  
 A.C. Air Conditioning  
 A.P. Air Pump  
 A.T.F. Automatic Transmission Fluid  
 ABDS Accessory Belt Drive System  
 Accy. Accessory  
 Adj. Adjustable  
 Adjmt. Adjustment  
 ADP Alternator Decoupler Pulley  
 Air-Hyd. Air Over Hydraulic  
 Almn. Aluminum  
 Alt. Alternator  
 Assy. Assembly  
 Auto. Automatic  
 Aux. Auxiliary  
 AWD All Wheel Drive  
 B.B.C. Bumper To Back Of Cab  
 Bbl. Barrel  
 Brkt. Bracket  
 C. Celsius  
 C.I.D. Cubic Inch Displacement  
 C.O.E. Cab Over Engine  
 C.S. Crankshaft  
 Calif. California  
 Cam. Camshaft  
 Carb. Carburetor  
 Cat. Caterpillar  
 CC (cc) Cubic Centimeter(s)  
 CDC Consolidated Diesel Corporation  
 Chry. Chrysler  
 Circ. Circumference  
 CNG Compressed Natural Gas  
 Co. Company  
 Comm. Commercial  
 Compr. Compressor  
 Cond. Conditioning(er)  
 Conv. Conventional  
 Cool. Cooling  
 Corp. Corporation  
 Cu. Cubic  
 Cust. Custom  
 CVT Continuously Variable Transmission  
 Cyl. Cylinder  
 DEF Diesel Emissions Fluid  
 Deg. Degree  
 Dia. Diameter  
 Dlr. Dealer  
 DOHC Dual Overhead Cam  
 DOT Department of Transportation  
 DPFE Differential Pressure Feedback EGR  
 E.E.C. Evaporative Emission Control  
 E.G.R. Exhaust Gas Recirculation  
 EBS Electronic Braking System  
 Elec. Electric  
 Eng. Engine  
 EPDM Ethylene Propylene Diene Monomer  
 Equip. Equipped, Equipment  
 Evap. Evaporative  
 Exc. Except

Exch. Exchanger  
 Ext. External  
 F. Fahrenheit  
 Fed. Federal  
 FHP Fractional Horse Power  
 FWD Front Wheel Drive  
 Ft. Foot (Feet)  
 G.V.W. Gross Vehicle Weight  
 Gal. Gallon  
 Gas. Gasoline  
 Gen. Generator  
 GM General Motors  
 GMC General Motors Corporation  
 Gov. Governor  
 H.D. Heavy Duty  
 H.O. High Output  
 H.P. Horsepower  
 Hemi. Hemispherical  
 Hi Perf. High Performance  
 Horiz. Horizontal  
 Hyd. Hydraulic  
 Hydra. Hydramatic  
 Hydro. Hydrostatic  
 Hz Hertz  
 I.C. Inside Circumference  
 I.D. Inside Diameter  
 ID Identification  
 In. Inch (Inches)  
 In. Hg. Inch of Mercury  
 Inc. Increased  
 Incl. Includes  
 Ind. Industrial  
 Inj. Injection  
 Inst. Installed  
 Install. Installation  
 J.S. Jack Shaft  
 L. Litre  
 L.C.F. Low Cab Forward  
 L.C.I. Low Cut-In  
 L.D. Light Duty  
 Lb. (Lbs.) Pound(s)  
 Limo. Limousine  
 LPG Liquid Petroleum Gas  
 m Meters  
 M.D. Medium Duty  
 Mach. Machine  
 Man. Manual  
 Max. Maximum  
 Mech. Mechanical  
 Mfg. Manufacturing  
 Mfr. Manufacturer  
 MHz Megahertz  
 Min. Minimum  
 mm Millimeter  
 MPI Multi-Port Injection  
 Mtd. Mounted  
 Mtr. Motor  
 No. Number  
 Nom. Nominal

O.C. Outside Circumference  
 O.D. Outside Diameter  
 O.H.C. Overhead Cam  
 O.H.V. Overhead Valve  
 OE Original Equipment  
 OEM Original Equipment Manufacturer  
 P.S. Power Steering  
 Psi Pound per Square Inch  
 P.T.O. Power Take-Off  
 Pass. Passenger  
 PCV Positive Crankcase Ventilation  
 Perf. Performance  
 Pkg. Package  
 Press. Pressure  
 Prod. Production  
 Pt. No. Part Number  
 R.P.M. Revolutions per Minute  
 Rad. (Rads.) Radiator(s)  
 Rec. Recreational  
 Repl. Replacement  
 RWD Rear Wheel Drive  
 S.P. Steering Pump  
 SBDS Synchronous Belt Drive System  
 Ser. Serial  
 SHO Super High Output  
 SOHC Single Overhead Cam  
 Spec. Special  
 Sq. Square  
 Std. Standard  
 Stg. Steering  
 Strt. Straight  
 Susp. Suspension  
 SVT Special Vehicle Teams  
 T.W. Top Width  
 Temp. Temperature  
 Trans. Transmission  
 Trlr. Trailer  
 Trk. Truck  
 TSB Technical Service Bulletin  
 Turbo Turbocharged  
 V. Volts  
 V.P. Vacuum Pump  
 V.S. Variable Speed  
 Vac. Vacuum  
 Vert. Vertical  
 VIN Vehicle Identification Number  
 VIO Vehicles in Operation  
 VTEC Variable Valve Timing & Lift Electronic Control  
 W/ With  
 W/O Without  
 W. Watts  
 W.B. Wheelbase  
 W.P. Water Pump  
 X.C. (XC) Extra Cooling  
 2WD 2 Wheel Drive  
 4WD 4 Wheel Drive  
 4WS 4 Wheel Steering



Manufacturers' Part Number Shown for Reference Only

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE</b>				<b>ACE HARDWARE - Continued</b>			
<b>13AH660F</b>				<b>131-412; 131-414 - Continued</b>			
Eng. To Deck .....	7540329A		6630BR	Trans. ....	7540101		6517BR
Eng. To V.S. ....	7540280A		6447BR				
V.S. To Trans. ....	7540370		6439BR	<b>131-425; 131-435</b>			
				Blade .....	7540127		6966
<b>13AM673G</b>				Drive .....	7540135		6925
Eng. To Deck .....	7540371A		6402BR	Trans. ....	7540136		6931
Eng. To V.S. ....	7540280A		6447BR				
V.S. To Trans. ....	7540370		6439BR	<b>131-480; 131-490</b>			
				Blade .....	7540145		6488BR
<b>13AN673G</b>				Drive .....	7540147	3520	6952
Deck .....	7540371A		6402BR	Trans. ....	7540136		6931
Eng. ....	7540280A		6447BR				
Trans. ....	7540370		6439BR	<b>131-495</b>			
				Blade .....	7540145		6488BR
<b>13AN698G</b>				Drive; W/31" Belt O.C. ....	7540136		6931
Deck .....	7540371A		6402BR	Drive; W/52" Belt O.C. ....	7540147	3520	6952
Fan .....	7540441		6417BR				
				<b>132-380</b>			
<b>13AS608G</b>				Blade; W/50" Belt O.C. ....	7540138	3500	6950
Drive .....	7540468		6556BR	Blade; W/64" Belt O.C. ....	7540167		6964
P.T.O.; W/Electric P.T.O. ....	7540485		6575BR	Trans. ....	7540164	2630	6863
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR				
Variable Speed .....	7540467		6606BR	<b>132-385</b>			
				Blade .....	7540138	3500	6950
<b>130-390</b>				Trans. ....	7540198		6451BR
Blade .....	7540107		6830				
Trans. ....	7540111	2450	6845	<b>132-412</b>			
				Blade .....	7540138	3500	6950
<b>130-395</b>				Trans. ....	7540101		6517BR
Blade .....	7540167		6964				
Drive .....	7540198		6451BR	<b>132-435</b>			
				Blade .....	7540127		6966
<b>130-400</b>				Drive .....	7540135		6925
Blade .....	7540188		6951	Trans. ....	7540136		6931
Trans. ....	7540101		6517BR				
				<b>132-460</b>			
<b>130-410</b>				Blade .....	7540118		6963
Blade .....	7540138	3500	6950	Trans. ....	7540166		6962
Trans. ....	7540101		6517BR				
				<b>132-480</b>			
<b>130-420; 130-430</b>				Blade .....	7540151		6967
Blade .....	7540127		6966	Deck .....	7540138	3500	6950
Drive .....	7540135		6925	Traction .....	7540136		6931
Trans. ....	7540136		6931				
				<b>132-495</b>			
<b>130-460</b>				Blade .....	7540145		6488BR
Blade .....	7540118		6963	Eng. To Variator .....	7540138		6950
Trans. ....	7540937	3590	6959	Variator To Trans. ....	7540136		6931
<b>130-466</b>				<b>133-380</b>			
Blade .....	7540151		6967	Blade; W/50" Belt O.C. ....	7540138	3500	6950
Deck .....	7540138	3500	6950	Blade; W/64" Belt O.C. ....	7540167		6964
Traction .....	7540136		6931	Trans. ....	7540164	2630	6863
<b>130-470</b>				<b>133-385</b>			
Blade .....	7540118		6963	Blade .....	7540138	3500	6950
Trans. ....	7540937	3590	6959	Trans. ....	7540198		6451BR
<b>130-480</b>				<b>133-410</b>			
Blade .....	7540145		6488BR	Blade .....	7540138	3500	6950
Drive .....	7540147	3520	6952	Trans. ....	7540101		6517BR
Trans. ....	7540136		6931				
				<b>133-435</b>			
<b>130-498</b>				Blade .....	7540127		6966
Blade .....	7540145		6488BR	Drive .....	7540135		6925
Trans. ....	7540226		6551BR	Trans. ....	7540136		6931
<b>130-780</b>				<b>133-460</b>			
Deck; W/Optional 44" Deck .....	7540230		6755BR	Blade; W/50" Belt O.C. ....	7540138	3500	6950
Drive .....	7540245		6859	Blade; W/67" Belt O.C. ....	7540151		6967
Transaxle .....	7540255		6837	Deck .....	7540101		6517BR
				Trans. ....	7540136		6931
<b>131-360</b>				<b>133-485</b>			
Blade .....	7540107		6830	Blade .....	7540151		6967
Trans. ....	7540936		6847	Trans. ....	7540127		6966
<b>131-385</b>				<b>133-495</b>			
Drive .....	7540136		6931	Blade .....	7540145		6488BR
Trans. ....	7540147	3520	6952	Drive; W/37" Belt O.C. ....	7540173	3370	6937
				Drive; W/66" Belt O.C. ....	7540127		6966
<b>131-412; 131-414</b>							
Blade .....	7540138	3500	6950				

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE - Continued</b>			
<b>134-380</b>			
Blade .....	7540138	3500	6950
Trans.; W/62" Belt O.C. ....	7540198		6451BR
Trans.; W/63" Belt O.C. ....	7540164	2630	6863
<b>134-385</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>134-400</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>134-435</b>			
Blade .....	7540127		6966
Drive .....	7540135		6925
Trans. ....	7540136		6931
<b>134-445; 134-455</b>			
Blade .....	7540178	3820	6982
Drive .....	7540185		6849
<b>134-460</b>			
Blade .....	7540151	3670	6967
Deck .....	7540138	3500	6950
Traction .....	7540136	3310	6931
<b>134-495</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>134-504</b>			
Blade .....	7540264		6639BR
Primary Variator .....	7540241		6494BR
Secondary Variator .....	7540240		6511BR
Trans. ....	7540249		6930
<b>134-585</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540136		6931
<b>134-597</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>134-638</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>134-699</b>			
Blade .....	7540271		6557BR
Drive .....	7540266		6775BR
<b>135-380; 135-385</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>135-435</b>			
Blade .....	7540127		6966
Drive .....	7540135		6925
Trans. ....	7540136		6931
<b>135-501</b>			
Blade; W/26" Deck .....	7540264		6639BR
Trans. ....	7540249		6930
<b>135-504</b>			
Eng. To Variator .....	7540241		6494BR
Variator To Trans. ....	7540240		6511BR
<b>135-704</b>			
Blade .....	7540293		6501BR
Deck .....	7540229		6852
<b>136-380; 136-385</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>136-390</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>136-400</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE - Continued</b>			
<b>136-435</b>			
Blade .....	7540127		6966
Drive .....	7540135		6925
Trans. ....	7540136		6931
<b>136-465</b>			
Blade .....	7540151		6967
Trans. ....	7540136		6931
<b>136-497</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>136-504</b>			
Blade .....	7540264		6639BR
Primary Variator .....	7540241		6494BR
Secondary Variator .....	7540240		6511BR
Trans. ....	7540249		6930
<b>136-525; 136-575</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>136-638</b>			
Deck .....	7540145		6488BR
Eng. To V.S. ....	7540280		6447BR
Transaxle .....	7540266		6775BR
V.S. To Trans. ....	7540281		6405BR
<b>136-705</b>			
Deck .....	7540293		6501BR
Eng. To Deck .....	7540229		6852
<b>137-390</b>			
Blade; W/54" Belt O.C. ....	7540195	2540	6854
Blade; W/64" Belt O.C. ....	7540167		6964
Drive .....	7540198		6451BR
<b>137-435</b>			
Blade .....	7540127		6966
Drive .....	7540135		6925
Trans. ....	7540136		6931
<b>137-465</b>			
Blade .....	7540151		6967
Deck .....	7540138	3500	6950
Traction .....	7540136	3310	6931
<b>137-497</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>137-504</b>			
Blade .....	7540264		6639BR
Eng. To Variator .....	7540241		6494BR
Trans. ....	7540249		6930
Variator To Trans. ....	7540240		6511BR
<b>137-525</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>138-090</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>138-360</b>			
Blade .....	7540935	2310	6831
Drive .....	7540936		6847
<b>138-390</b>			
Blade; W/54" Belt O.C. ....	7540195	2540	6854
Blade; W/64" Belt O.C. ....	7540167		6964
Drive .....	7540198		6451BR
<b>138-402</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>138-420</b>			
Blade .....	7540127		6966
Trans. ....	7540128		6935





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE - Continued</b>			
<b>138-460</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>138-460A</b>			
Blade .....	7540151	3670	6967
Deck .....	7540138	3500	6950
Traction .....	7540136	3310	6931
<b>138-462</b>			
Blade .....	7540151	3670	6967
Drive; W/31" Belt O.C. ....	7540136	3310	6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>138-462A</b>			
Blade .....	7540151		6967
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>138-465</b>			
Blade .....	7540151	3670	6967
Drive; W/31" Belt O.C. ....	7540136	3310	6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>138-497</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>138-498</b>			
Blade .....	7540225		6565
Trans. ....	7540226		6551BR
<b>138-641; 138-651</b>			
Deck; W/30" Rear Discharge 794 .....	7540328		6949
Deck; W/34" Rear Discharge 800 .....	7540151		6967
Deck; W/38" Side Discharge 801 .....	7540145		6488BR
Deck; W/38" Side Discharge 805 Deep ..	7540329		6630BR
<b>138-752</b>			
Cross Drive; W/44" Side Discharge 935 ..	7540293		6501BR
Cross Drive; W/46" Side Discharge 806 ..	7540349		6637BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Side Discharge 935 .....	7540230		6755BR
Deck; W/46" Side Discharge 806 .....	7540350		6464BR
Trans. ....	7540248		6431BR
<b>138-796; 138-797</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>139-395</b>			
Blade .....	7540167		6964
Drive .....	7540198		6451BR
<b>139-400</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>139-466</b>			
Blade .....	7540151		6967
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>139-498</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>139-796</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>140-660</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>140-760; 140-960</b>			
Drive .....	7540124		6857
P.T.O. ....	7540123		3V335
<b>141-669</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>141-960; 141-990</b>			
Drive .....	7540124		6857
P.T.O. ....	7540123		3V335

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE - Continued</b>			
<b>142-669</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>143-660; 143-760; 144-660; 144-672; 144-760; 145-760; 146-660</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>146-835</b>			
Blade .....	7540293		6501BR
Deck .....	7540230		6755BR
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540244		6840
<b>147-813</b>			
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540244		6840
<b>148-812</b>			
Cross Drive; W/44" Side Discharge 935 ..	7540293		6501BR
Deck; W/44" Side Discharge 935 .....	7540230		6755BR
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540244		6840
<b>70403</b>			
Blade .....	7540151		6967
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>71279</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>71280</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540139	7380	
Trans. ....	7540124		6857
<b>71308</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>71309</b>			
Blade .....	7540138	3500	6950
Eng. To Variator .....	7540135	3250	6925
Trans. ....	7540136	3310	6931
<b>71350</b>			
Deck; W/30" Rear Discharge 794 .....	7540328		6949
Deck; W/34" Side Discharge 800 .....	7540151		6967
Deck; W/38" Side Discharge 801 .....	7540145		6488BR
Deck; W/38" Side Discharge 805 Deep ..	7540329		6630BR
<b>71820</b>			
Gen. ....	7540139	1380	6738
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>71824</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
Trans. ....	7540127		6966
<b>71826</b>			
Gen. ....	7540169		3V355
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>72057; 72095</b>			
Blade .....	7540138		6950
Trans. ....	7540164		6863
<b>72239</b>			
Blade; 1973 .....			6967
Blade; 1974 .....	7540145		6488BR
Drive; W/37" Belt O.C.; 1974 .....	7540173	3370	6937
Drive; W/65" Belt O.C.; 1974 .....	7540191	2650	6865
Trans.; 1973 .....			6966

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE - Continued</b>			
<b>72240</b>			
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>72420</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>72426</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....		3370	6937
Drive; W/66" Belt O.C. ....			6966
Variator To Trans. ....	7540173	3370	6937
<b>72428; 72429</b>			
Blade .....	7540178	3820	6982
Trans.; W/48" Belt O.C.; 1975 .....	7540200		6848
Trans.; W/49" Belt O.C.; 1974 .....	7540185		6849
<b>72430</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>72561</b>			
Blade .....	7540151		6967
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>72567</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>72770</b>			
Deck; W/30" Rear Discharge 794 .....	7540328		6949
Deck; W/34" Side Discharge 800 .....	7540151		6967
Deck; W/38" Side Discharge 801 .....	7540145		6488BR
Deck; W/38" Side Discharge 805 Deep ..	7540329		6630BR
<b>72771</b>			
Deck; W/44" Side Discharge 931 .....	7540230		6755BR
Deck; W/46" Side Discharge 806 .....	7540350		6464BR
Drive; W/44" Rear Discharge 931 .....	7540260		5716
Drive; W/46" Side Discharge 806 .....	7540349		6637BR
<b>AGCO</b>			
<b>520H</b>			
Deck Drive; W/38" Deck; W/Narrow			
Pulley .....	1723025		6714BR
Trans. ....	1728008		6709BR
<b>522H</b>			
Deck Drive; W/44" Deck .....	1729627		6848BR
Trans. ....	1728008		6709BR
<b>524H</b>			
Deck Drive; W/50" Deck; W/Narrow			
Pulley .....	1703466		6484BR
Trans. ....	1728008		6709BR
<b>1620H</b>			
Arbor; W/44" Deck .....	1721532		6798BR
Arbor; W/50" Deck .....	1703836		6524BR
Eng. To P.T.O.; W/44" Deck .....	1601672		6799BR
Eng. To P.T.O.; W/50" Deck .....	1707740		6869
Trans. ....	1726841		6710BR
<b>1723H</b>			
Arbor; W/50" Deck .....	1703836		6524BR
Eng. To P.T.O.; W/50" Deck .....	1707740		6869
Trans. ....	1721392		6710BR
<b>1825H; 1827H</b>			
Arbor; W/50" Deck .....	1703836		6524BR
Arbor; W/54" Deck .....	1671076		6765BR
Eng. To P.T.O.; W/50" Deck .....	1707740		6869
Eng. To P.T.O.; W/54" Deck .....	1722039		6525BR
Trans. ....	1721393		6710BR
<b>2027H; 2027LC</b>			
Arbor; W/48" Deck .....	174911		6844
Eng. To P.T.O.; W/48" Deck .....	1725557		6860

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AGCO - Continued</b>			
<b>2027H; 2027LC - Continued</b>			
Eng. To P.T.O.; W/60" Deck .....	1725154		6756BR
<b>AGWAY</b>			
<b>52-1302</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>52-1303</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>82-0310</b>			
Blade; W/25" Deck .....	7540138	3500	6950
Blade; W/30" Deck .....	7540167	3640	6964
Trans. ....	7540164	2630	6863
<b>82-0311</b>			
Blade; W/30" Belt O.C. ....	7540107	2300	6830
Blade; W/52" Belt O.C. ....	7540147	3520	6952
Eng. To Variator .....	7540135	3250	6925
Trans. ....	7540936	2470	6847
Variator To Trans. ....	7540136	3310	6931
<b>82-0312</b>			
Blade .....	7540167		6964
Drive .....	7540164	2630	6863
<b>82-0313</b>			
Blade .....		3660	6966
Eng. To Variator .....	7540136	3310	6931
<b>82-0315</b>			
Blade .....	7540145		6488BR
Drive .....	7540173	3370	6937
<b>82-0350</b>			
Blade .....	7540167		6964
Drive .....	7540164	2630	6863
<b>82-0351</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540185		6849
<b>82-0352</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>82-0356</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>82-0411</b>			
Blade .....	7540147	3520	6952
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>82-0412; 82-0413</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>82-0414</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>82-0420</b>			
Blade .....	7540147	3520	6952
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>82-0421</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>82-0424</b>			
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
<b>82-0503</b>			
Gen. ....	7540169	7355	
P.T.O. ....	7540164	2630	6863



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AGWAY - Continued</b>			
<b>82-2220</b>			
Blade .....	7540249		6930
Trans. ....	7540264		6639BR
<b>82-2221</b>			
Eng. To Deck .....	7540264		6639BR
Primary Variator .....	7540241		6494BR
Secondary Variator .....	7540240		6511BR
<b>82-2223</b>			
Deck .....	7540151	3670	6967
<b>82-2225</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>82-2228</b>			
Deck .....	7540329		6630BR
Trans., W/Peerless Trans. ....	7540266		6775BR
<b>82-2259</b>			
Blade .....	7540188	3510	6951
Trans. ....	7540101		6517BR
<b>82-2261</b>			
Blade .....	7540167		6964
Fan & Alt.; Ser. No. 010860 & After .....	7540164		6863
Trans. ....		2630	
<b>82-2263</b>			
Blade .....	7540151	3670	6967
Eng. To Variator .....	7540138	3500	6950
Variator To Trans. ....	7540136	3310	6931
<b>82-2265</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>82-2267</b>			
Deck .....	7540198		6451BR
Drive .....	7540207		6842
<b>82-2270</b>			
Blade .....	7540167		6964
Drive .....	7540198		6451BR
<b>82-2271</b>			
Blade .....	7540145		6488BR
Trans.; W/82" Belt O.C. ....	7540226		6551BR
Trans.; W/85" Belt O.C. ....	7540266		6775BR
<b>82-2274</b>			
Blade .....	7540145		6488BR
Drive .....	7540138	3500	6950
Trans. ....	7540136	3310	6931
<b>82-5000</b>			
Drive .....	7540227		6963
Transaxle .....	7540212		6945
<b>82-5001</b>			
P.T.O. ....	7540234		6841
<b>82-5008</b>			
Trans. ....	7540217		6979
<b>82-5009</b>			
Blade .....	7540184		6852
Drive; W/54" Belt O.C. ....	7540180		6510BR
Drive; W/81" Belt O.C. ....	7540182	3810	6981
Gen. ....	7540134	7330	
<b>82-5010</b>			
Gen. ....	7540134	7330	
<b>82-5030</b>			
Gen. ....	7540169	7355	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>82-5058; 82-5059</b>			
Drive; W/45" Belt O.C. ....	7540212		6945
Drive; W/60" Belt O.C. ....	7540210		6960
<b>82-5060</b>			
Drive .....	7540227	3630	6963
Transaxle .....	7540212	3450	6945

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AGWAY - Continued</b>			
<b>82-5131</b>			
Blade .....	7540293		6501BR
Deck .....	7540230		6755BR
Eng. To J.S. ....	7540245	2590	6859
J.S. To Trans. ....	7540177	2320	6832
<b>82-5132</b>			
Eng. To J.S. ....	7540245	2590	6859
J.S. To Trans. ....	7540244	2400	6840
<b>82-5140</b>			
Blade .....	7540293		6501BR
Deck .....	7540230		6755BR
Trans. ....	7540248		6431BR
<b>82-5214</b>			
Deck; W/Optional 44" Deck .....	7540230		6755BR
Drive .....	7540245	2590	6859
J.S. To Trans. ....	7540154	2370	6837
Transaxle .....	7540255		6837
<b>82-5215</b>			
Drive .....	7540227	3630	6963
Transaxle .....	7540212	3450	6945
<b>82-5300</b>			
P.T.O. ....	7540165		6834
<b>130-410</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>130-415</b>			
Blade .....	7540147	3520	6952
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>130-420; 130-430</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>130-460</b>			
Blade .....	7540118	3630	6963
Trans. ....	7540937	3590	6959
<b>130-490</b>			
Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
<b>131-418</b>			
Blade .....	7540147	3520	6952
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>131-425; 131-435</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>131-480; 131-495</b>			
Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
<b>132-380; 132-390</b>			
Blade; W/25" Deck .....	7540138	3500	6950
Blade; W/30" Deck .....	7540167	3640	6964
Trans. ....	7540164	2630	6863
<b>132-418</b>			
Blade .....	7540147	3520	6952
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>132-425; 132-435</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>132-480</b>			
Blade .....	7540151		6967
Drive .....	7540138	3500	6950
Trans. ....	7540136		6931

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AGWAY - Continued</b>			
<b>132-495</b>			
Blade .....	7540145		6488BR
Drive .....	7540138	3500	6950
Trans. ....	7540136		6931
<b>133-390</b>			
Blade .....	7540167		6964
Drive .....	7540164	2630	6863
<b>133-420</b>			
Blade .....	7540147	3520	6952
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>133-440; 133-445</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540179		6950
<b>133-460</b>			
Blade .....	7540151		6967
Drive .....	7540138	3500	6950
Trans. ....	7540136		6931
<b>133-485</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>133-495</b>			
Blade .....	7540145		6488BR
Trans. ....	7540127		6966
<b>134-390</b>			
Blade .....	7540167		6964
Drive .....	7540164	2630	6863
<b>134-400</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>134-445</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540185		6849
<b>134-485</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>134-495</b>			
Blade .....	7540145		6488BR
Drive .....	7540191		6865
Trans. ....	7540173	3370	6937
<b>135-445</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540185	2490	6849
<b>135-495</b>			
Blade .....	7540145		6488BR
Eng. To J.S. ....	7540191	2650	6865
J.S. To Trans. ....	7540173	3370	6937
<b>135-501</b>			
Deck; W/26" Mower .....	7540264		6639BR
Trans. ....	7540249	3300	6930
<b>135-697</b>			
Trans. ....	7540266		6775BR
<b>136-725</b>			
Transaxle .....	7540248		6431BR
<b>138-633</b>			
Deck; W/30" Discharge 794; W/Single Cyl. Eng. ....	7540328	3490	6949
Deck; W/34" Discharge 800; W/Single Cyl. Eng. ....	7540151	3670	6967
Deck; W/38" Discharge 805 Deep; W/Single Cyl. Eng. ....	7540329		6630BR
Deck; W/Single Cyl. Eng. ....	37X40		6451BR
Primary; W/Single Cyl. Eng. ....	37X11		6452BR
<b>139-390</b>			
Blade .....	7540105		6830
Trans. ....	7540111	2450	6845
<b>139-410</b>			
Blade .....	7540138	3500	6950

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AGWAY - Continued</b>			
<b>139-410 - Continued</b>			
Trans. ....	7540101		6517BR
<b>139-470</b>			
Blade .....	7540118		6963
Gen. ....	7540134	7330	
Trans. ....	7540937	3590	6959
<b>144-760</b>			
Trans. ....	7540182	3810	6981
<b>144-990</b>			
P.T.O. ....	7540165	2340	6834
Trans. ....	7540124	2570	6857
<b>145-843</b>			
Eng. To J.S. ....	7540245	2590	6859
J.S. To Trans. ....	7540177	2320	6832
<b>149-740</b>			
Blade .....	7540118		6963
Gen. ....	7540134	7330	
Trans. ....	7540937	3590	6959
<b>AIRCAP</b>			
<b>137-502</b>			
Eng. To Variator .....	7540241		6494BR
Variator To Trans. ....	7540240		6511BR
<b>137-504</b>			
Drive; W/35" Belt O.C. ....	7540241		6494BR
Drive; W/38" Belt O.C. ....	7540240		6511BR
<b>527</b>			
Blade .....	7540195A		6854
Trans. ....	7540198		6451BR
<b>1020</b>			
Blade; W/8 H.P. Eng.; W/30" Deck .....	7540264		6639BR
<b>1100</b>			
Blade; W/11 H.P. Eng.; W/38" Deck .....	7540145		6488BR
<b>ER7130</b>			
Blade .....	10720		6974
Transaxle .....	10713		6370
<b>R4124; R5124</b>			
Blade .....	10722		6851
Transaxle .....	10713		6370
<b>R7130A</b>			
Blade .....	10720		6974
Transaxle .....	10713		6370
<b>AIR-ELECTRIC</b>			
<b>380</b>			
Eng. To J.S.; W/10 H.P. Eng. ....			6942
J.S. To Blade; W/10 H.P. Eng. ....			6929
<b>DS-25; DS-30</b>			
Belt; W/26" Belt O.C. ....	SD13	3260	6926
Belt; W/35" Belt O.C. ....		2350	6835
Belt; W/53" Belt O.C. ....	SD12	3530	6953
<b>ALDENS</b>			
<b>131-410</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>136-380; 136-385</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>136-460; 136-465</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>380-002; 390-002</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>650-002; 660-002</b>			
Belt; W/6 H.P. Eng. ....	7540112	3800	6980



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALDENS - Continued</b>			
7506X; 7507X			
Trans. ....	7540124	2570	6857
<b>ALLIED HARDWARE</b>			
4-385			
Blade .....	7540138	3500	6950
Trans. ....	7540164	2630	6863
4-390; 4-395			
Blade .....	7540167	3640	6964
Trans. ....	7540164	2630	6863
30-132			
Blade .....	7540935	2310	6831
Trans. ....	7540108	2640	6864
130-415			
Blade .....	7540147	3520	6952
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
130-420; 130-430			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
130-460; 130-470			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
130-480			
Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
131-418			
Blade .....	7540147	3520	6952
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
131-425; 131-435			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
131-480; 131-490			
Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
132-380			
Blade; W/50" Belt O.C. ....	7540138	3500	6950
Blade; W/64" Belt O.C. ....	7540167		6964
Trans. ....	7540164	2630	6863
132-412			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
132-418			
Blade .....	7540147	3520	6952
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
132-425; 132-435			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
132-480			
Blade .....	7540151		6967
Drive .....	7540138	3500	6950
Trans. ....	7540136		6931
132-495			
Blade .....	7540145		6488BR
Drive .....	7540138	3500	6950
Trans. ....	7540136		6931
133-390; 133-395			
Blade; W/50" Belt O.C. ....	7540138	3500	6950
Blade; W/64" Belt O.C. ....	7540167		6964
Trans. ....	7540164	2630	6863
133-420; 133-424			
Blade .....	7540147	3520	6952

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIED HARDWARE - Continued</b>			
133-420; 133-424 - Continued			
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
133-430; 133-434			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
133-460; 133-465			
Blade .....	7540138	3500	6950
Drive .....	7540101		6517BR
Trans. ....	7540136		6931
133-495			
Blade .....	7540145		6488BR
Trans. ....	7540127		6966
Variable Speed .....	7540173	3370	6937
134-385			
Blade .....	7540138	3500	6950
Drive .....	7540164	2630	6863
134-390			
Blade .....	7540167		6964
Drive .....	7540164	2630	6863
134-400			
Blade .....	7540188		6951
Drive .....	7540101		6517BR
134-435			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
134-445			
Blade .....	7540178	3820	6982
Drive .....	7540185		6849
134-465			
Blade .....	7540151		6967
Drive .....	7540138	3500	6950
Trans. ....	7540136		6931
134-495			
Blade .....	7540167		6964
Drive .....	7540164	2630	6863
138-362			
Blade .....	7540935	2310	6831
Trans. ....	7540936		6847
138-390			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
138-460			
Blade; W/31" Belt O.C. ....	7540935	2310	6831
Blade; W/63" Belt O.C. ....	7540118		6963
Trans.; W/45" Belt O.C. ....	7540111	2450	6845
Trans.; W/59" Belt O.C. ....	7540937	3590	6959
141-669; 142-669			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
145-832			
Eng. To J.S. ....	7540245	2590	6859
J.S. To Trans. ....	7540244	2400	6840
145-842			
Eng. To J.S. ....	7540245	2590	6859
J.S. To Trans. ....	7540177	2320	6832
145-882			
Eng. To J.S. ....	7540245	2590	6859
J.S. To Trans. ....	7540244	2400	6840
145-918			
Eng. To Variator .....	7540227	3630	6963
P.T.O. ....	7540229	2520	6852
Variator To Trans. ....	7540212	3450	6945
340-132			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS</b>				<b>ALLIS-CHALMERS - Continued</b>			
<b>310; 312; 314</b>				<b>516G</b>			
Arbor; W/42" Deck .....	2025364		6434BR	Drive; Mfr. No. 1692829 .....	1657044		6521BR
Arbor; W/48" Deck .....	1603075		6457BR	<b>516H</b>			
Belt; W/83" Belt O.C. ....	1604406		6444BR	Drive; Mfr. No. 1692831 .....	1719819		6434BR
Belt; W/88" Belt O.C.; W/36" Deck .....	2027639		6988	Drive; Mfr. No. 1693098, 1693343,			
Belt; W/96" Belt O.C.; W/36" Deck .....	2027624		6996	1693542 .....	1717397		6798BR
Forward .....	2029350		6853	<b>517H</b>			
Front P.T.O.; W/42" Deck .....	1607812		6558BR	Drive; Mfr. No. 1693544 .....	1717397		6798BR
Front P.T.O.; W/48" Deck .....	1604406		6444BR	<b>526</b>			
Hydro .....	1602969		6848	Mower Drive .....	1664946		6857
Rear P.T.O. ....	2026324	2910	6891	Trans. ....	1665706		6839
Reverse .....	2029348		6834	<b>608</b>			
<b>405</b>				Arbor; W/36" Deck .....	2027134		6870
Mower .....	2029223	2440	6844	Belt; W/42" Deck .....	2025364		6434BR
Trans. ....	2028241	2310	6831	Deck .....	108505		6870
<b>409G</b>				Drive .....	1666698		6643BR
Drive; Mfr. No. 1692177, 1692394 .....	1676460		6843	Mower; W/36" Deck .....	2087732		6878
<b>410</b>				Trans. ....	2028035		6775BR
Arbor; W/42" Deck .....	2025364		6434BR	<b>610</b>			
Arbor; W/48" Deck .....	1603075		6457BR	Arbor; W/36" Deck .....	2027134		6870
Belt; W/84" Belt O.C. ....	1605816		6811BR	Belt; W/70" Belt O.C. ....	2027134		6870
Belt; W/85" Belt O.C. ....	2028035		6775BR	Belt; W/82" Belt O.C.; W/42" Deck .....	2025364		6434BR
Belt; W/87" Belt O.C. ....	2029622		6870	Belt; W/85" Belt O.C. ....	2028035		6775BR
Belt; W/88" Belt O.C.; W/36" Deck .....	2027639		6988	Mower; W/36" Deck .....	2087732		6878
Belt; W/96" Belt O.C.; W/36" Deck .....	2027624		6996	<b>611</b>			
Drive .....	2028474		6849	Arbor; W/36" Deck .....	2027134		6870
Forward .....	2029350		6853	Deck .....	108505		6870
Front P.T.O.; W/42" Deck .....	1607812		6558BR	Drive .....	1666698		6643BR
Front P.T.O.; W/48" Deck .....	1604406		6444BR	Mower; W/36" Deck .....	2087732		6878
Hydro .....	1602969		6848	Trans. ....	2028035		6775BR
Reverse .....	2029348		6834	<b>611H</b>			
<b>411G</b>				Blade .....	2027134		6870
Drive; Mfr. No. 1692819, 1693042,				Drive .....	1666698		6643BR
1693315 .....	1676460		6843	<b>612</b>			
<b>412</b>				Eng. To Deck .....	108505		6870
Forward .....	2029350		6853	<b>612G</b>			
Hydro .....	1602969		6848	Drive; Mfr. No. 1691428 .....	1716854		6643BR
Reverse .....	2029348		6834	<b>612H</b>			
<b>412G</b>				Drive; Mfr. No. 1691933 .....	1656960		6811BR
Drive; Mfr. No. 1692175, 1692396 .....	1676460		6843	<b>612HST</b>			
<b>414; 416</b>				Drive; Mfr. No. 1691432 .....	1703836		6524BR
Arbor; W/42" Deck .....	2025364		6434BR	Drive; Mfr. No. 1691479 .....	1670835		6458BR
Arbor; W/48" Deck .....	1603075		6457BR	<b>613</b>			
Belt; W/84" Belt O.C. ....	1605816		6811BR	Eng. To Deck .....	1668065		6869
Belt; W/85" Belt O.C. ....	2028035		6775BR	<b>613H</b>			
Belt; W/87" Belt O.C. ....	2029622		6870	Drive; Mfr. No. 1691477 .....	1672135		6523BR
Belt; W/88" Belt O.C.; W/36" Deck .....	2027639		6988	<b>616</b>			
Belt; W/96" Belt O.C.; W/36" Deck .....	2027624		6996	Belt .....	2028988		6949
Forward .....	2029350		6853	Drive .....	1655069	2240	6524BR
Front P.T.O.; W/42" Deck .....	1607812		6558BR	Front P.T.O. ....	2028459		6824
Front P.T.O.; W/48" Deck .....	1604406		6444BR	P.T.O. To Hitch .....	2029065		68100
Hydro .....	1602969		6848	Sicklebar .....	2029056		6857
Reverse .....	2029348		6834	<b>616H</b>			
<b>508</b>				Drive; Mfr. No. 1691475 .....	1672135		6523BR
Blade .....	2029582		A133	<b>620</b>			
Drive .....	2029660		6862	Belt .....	2028988		6949
P.T.O. To Mower .....	2029582		A133	Drive .....	1655069	2240	6524BR
<b>512G</b>				Front P.T.O. ....	2028459		6824
Drive; Mfr. No. 1692055 .....	1716854		6643BR	P.T.O. To Hitch .....	2029065		68100
Drive; Mfr. No. 1692096, 1692166,				Sicklebar .....	2029056		6857
1692409 .....	1708114		6895	<b>700</b>			
<b>512H</b>				Blade .....	1666801		6640BR
Drive; Mfr. No. 1692057, 1692164 .....	1656960		6811BR	Drive; W/36" Tiller .....	2027624		6996
Drive; Mfr. No. 1692263, 1692412 .....	170164		6877	Dual Range Drive .....	1607967		6639BR
<b>514G</b>				Forward .....	2029348		6834
Drive; Mfr. No. 1692595, 1693092,				Hydro .....	1650502		6422BR
1693339 .....	1657044		6521BR	P.T.O. ....	2026324	2910	6891
<b>514H</b>				Reverse .....	2029350		6853
Drive; Mfr. No. 1692588 .....	1672135		6523BR				
Drive; Mfr. No. 1693094, 1693341 .....	1717397		6798BR				
<b>515H</b>							
Drive; Mfr. No. 1693540 .....	1717397		6798BR				





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS - Continued</b>			
<b>710</b>			
Belt; W/66" Belt O.C. ....	2087759		6866
Belt; W/88" Belt O.C. ....	2027639		6988
Belt; W/96" Belt O.C. ....	2027624		6996
Blade .....	1666801		6640BR
Blower .....	2026755		6839
Drive; W/36" Tiller .....	2027624		6996
Drive; W/66" Belt O.C. ....	2087778		6866
Drive; W/70" Belt O.C. ....	2027134		6870
Dual Range Drive .....	1607967		6639BR
Forward .....	2029348		6834
Hydro. ....	1650502		6422BR
Mower .....	2029223		6844
P.T.O. ....	2026324	2910	6891
Reverse .....	2029350		6853
<b>712</b>			
Belt; W/66" Belt O.C. ....	2087759		6866
Belt; W/88" Belt O.C. ....	2027639		6988
Belt; W/96" Belt O.C. ....	2027624		6996
Blade; Ser. No. 1690021 & After; W/48" Deck .....	2027114		6885
Blade; W/80" Belt O.C. ....	1666801		6640BR
Blade; W/82" Belt O.C.; W/42" Deck .....	2025364		6434BR
Blade; W/84" Belt O.C.; W/42" Deck .....	1656960		6811BR
Blower .....	2026755		6839
Drive; Ser. No. 1690272 & After; W/48" Deck .....	2087648		6872
Drive; W/36" Tiller .....	2027624		6996
Drive; W/66" Belt O.C. ....	2087778		6866
Drive; W/70" Belt O.C. ....	2027134		6870
Dual Range Drive .....	1607967		6639BR
Forward .....	2029348		6834
Hydro. ....	1650502		6422BR
Mower .....	2029223		6844
P.T.O.; W/74" Belt O.C.; W/42" Deck .....	2087836		6874
P.T.O.; W/78" Belt O.C.; W/42" Deck .....	2087732		6878
P.T.O.; W/91" Belt O.C. ....	2026324	2910	6891
Reverse .....	2029350		6853
<b>712H; 712S</b>			
Blade .....	1666801		6640BR
Blower .....	2026755		6839
Drive; W/36" Tiller .....	2027624		6996
Drive; W/70" Belt O.C. ....	2027134		6870
Dual Range Drive .....	1607967		6639BR
Forward .....	2029348		6834
Hydro. ....	1650502		6422BR
P.T.O. ....	2026324	2910	6891
Reverse .....	2029350		6853
<b>716</b>			
Belt; W/66" Belt O.C. ....	2087759		6866
Belt; W/88" Belt O.C. ....	2027639		6988
Belt; W/96" Belt O.C. ....	2027624		6996
Blade; Ser. No. 1690021 & After; W/48" Deck .....	2027114		6885
Blade; W/80" Belt O.C. ....	1666801		6640BR
Blade; W/82" Belt O.C.; W/42" Deck .....	2025364		6434BR
Blade; W/84" Belt O.C.; W/42" Deck .....	1656960		6811BR
Blower .....	2026755		6839
Drive; Ser. No. 1690272 & After; W/48" Deck .....	2087648		6872
Drive; W/36" Tiller .....	2027624		6996
Drive; W/66" Belt O.C. ....	2087778		6866
Drive; W/70" Belt O.C. ....	2027134		6870
Dual Range Drive .....	1607967		6639BR
Forward .....	2029348		6834
Hydro. ....	1650502		6422BR
Mower .....	2029223		6844
P.T.O.; W/74" Belt O.C.; W/42" Deck .....	2087836		6874
P.T.O.; W/78" Belt O.C.; W/42" Deck .....	2087732		6878
P.T.O.; W/91" Belt O.C. ....	2026324	2910	6891
Reverse .....	2029350		6853
<b>716H</b>			
Blade .....	1666801		6640BR
Blower .....	2026755		6839
Drive; W/36" Tiller .....	2027624		6996
Drive; W/70" Belt O.C. ....	2027134		6870
Dual Range Drive .....	1607967		6639BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS - Continued</b>			
<b>716H - Continued</b>			
Forward .....	2029348		6834
Hydro. ....	1650502		6422BR
P.T.O. ....	2026324	2910	6891
Reverse .....	2029350		6853
<b>718</b>			
Belt; W/66" Belt O.C. ....	2087759		6866
Belt; W/88" Belt O.C. ....	2027639		6988
Belt; W/96" Belt O.C. ....	2027624		6996
Blade; Ser. No. 1690021 & After; W/48" Deck .....	2027114		6885
Blade; W/80" Belt O.C. ....	1666801		6640BR
Blade; W/82" Belt O.C.; W/42" Deck .....	2025364		6434BR
Blade; W/84" Belt O.C.; W/42" Deck .....	1656960		6811BR
Blower .....	2026755		6839
Drive; Ser. No. 1690272 & After; W/48" Deck .....	2087648		6872
Drive; W/36" Tiller .....	2027624		6996
Drive; W/66" Belt O.C. ....	2087778		6866
Drive; W/70" Belt O.C. ....	2027134		6870
Dual Range Drive .....	1607967		6639BR
Forward .....	2029348		6834
Hydro. ....	1650502		6422BR
Mower .....	2029223		6844
P.T.O.; W/74" Belt O.C.; W/42" Deck .....	2087836		6874
P.T.O.; W/78" Belt O.C.; W/42" Deck .....	2087732		6878
P.T.O.; W/91" Belt O.C. ....	2026324	2910	6891
Reverse .....	2029350		6853
<b>718H</b>			
Blade .....	1666801		6640BR
Drive; W/36" Tiller .....	2027624		6996
Dual Range Drive .....	1607967		6639BR
Forward .....	2029348		6834
Hydro. ....	1650502		6422BR
P.T.O. ....	2026324	2910	6891
Reverse .....	2029350		6853
<b>720</b>			
Drive .....	2028549	2240	6824
P.T.O. To Deck; W/60" Deck .....	2028766	2930	6893
Sicklebar Attachment; W/100" Belt O.C. ....	2029665		68100
Sicklebar Attachment; W/57" Belt O.C. ...	2029056		6857
<b>736</b>			
Blade .....	1610577		6856
J.S. ....	1610578		6825
Trans. ....	1601695		6843
<b>808; 810; 811</b>			
Arbor; W/36" Deck .....	2027134		6870
Blade; W/36" Mower .....	2027134		6870
Blade; W/42" Mower .....	2087732		6878
Blade; W/82" Belt O.C.; W/42" Deck .....	2025364		6434BR
Blade; W/84" Belt O.C.; W/42" Deck .....	1656960		6811BR
Drive; W/30" Rotary Mower .....	2087648		6872
Eng. To Deck; W/42" Mower .....	2025364		6434BR
Mower; W/36" Deck .....	2087732		6878
P.T.O.; W/74" Belt O.C.; W/42" Deck .....	2087836		6874
P.T.O.; W/78" Belt O.C.; W/42" Deck .....	2087732		6878
Trans. ....	2028035		6775BR
<b>830</b>			
Mower Drive .....	1665024		6854
Trans.; Mfr. No. 1691552 .....	1665706		6839
<b>836</b>			
Mower Drive .....	2087732		6878
Trans. ....			6839
<b>900; 910; 912; 914; 916</b>			
Arbor; W/42" Deck .....	1656960		6811BR
Belt; W/106" Belt O.C. ....	1657517		B103
Belt; W/66" Belt O.C. ....	2087759		6866
Blower; W/61" Belt O.C. ....	2027102	2610	6861
Blower; W/70" Belt O.C. ....	2027134		6870
Blower; W/77" Belt O.C. ....			6877
Drive; W/34" Belt O.C. ....	2029348		6834
Drive; W/53" Belt O.C. ....	2029350		6853
Dual Range Drive .....	1609767	2520	6852
Hydro. ....	1650502		6422BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS - Continued</b>			
<b>900; 910; 912; 914; 916 – Continued</b>			
P.T.O.; W/39" Belt O.C. ....	2026755		6839
P.T.O.; W/42" Deck .....	1666801		6640BR
P.T.O.; W/48" Deck .....	2087732		6878
P.T.O.; W/91" Belt O.C. ....	2026324	2910	6891
<b>916H</b>			
Arbor; W/42" Deck .....	1656960		6811BR
Belt; W/38" Deck .....	1657517		B103
Belt; W/66" Belt O.C. ....	2087759		6866
Blade .....			6878
Blower; W/61" Belt O.C. ....	2027102	2610	6861
Blower; W/70" Belt O.C. ....	2027134		6870
Blower; W/77" Belt O.C. ....			6877
P.T.O.; W/39" Belt O.C. ....	2026755		6839
P.T.O.; W/42" Deck .....	1666801		6640BR
P.T.O.; W/48" Deck .....	2087732		6878
<b>917</b>			
Drive; W/34" Belt O.C. ....	2029348		6834
Drive; W/53" Belt O.C. ....	2029350		6853
Dual Range Drive .....	1609767	2520	6852
Hydro .....	1650502		6422BR
P.T.O. ....	2026324	2910	6891
<b>917H</b>			
Drive; Mfr. No. 1691718, 1691960 .....	1650502		6422BR
<b>918H</b>			
Drive; Mfr. No. 1692144, 1692452, 1692846, 1692951, 1693413 .....	1650502		6422BR
Drive; W/P.S.; Mfr. No. 1692847, 1692941, 1693411 .....	1650502		6422BR
<b>919 Hydro</b>			
Arbor; W/42" Deck .....	1656960		6811BR
Belt; W/106" Belt O.C. ....	1657517		B103
Belt; W/66" Belt O.C. ....	2087759		6866
Blade .....			6878
Blower; W/61" Belt O.C. ....	2027102	2610	6861
Blower; W/70" Belt O.C. ....	2027134		6870
Blower; W/77" Belt O.C. ....			6877
P.T.O.; W/39" Belt O.C. ....	2026755		6839
P.T.O.; W/42" Deck .....	1666801		6640BR
P.T.O.; W/48" Deck .....	2087732		6878
<b>1030</b>			
Drive; Mfr. No. 1691995 .....	1665706		6839
<b>1030M</b>			
Drive; Mfr. No. 1692011 .....	1665706		6839
<b>1036</b>			
Blade .....			6878
Trans.; Mfr. No. 1691539 .....	1665706		6839
<b>1312G</b>			
Drive; Mfr. No. 1691658 .....	1678354		6842
<b>1613G</b>			
Drive; Mfr. No. 1691893 .....	1703836		6524BR
<b>1613H</b>			
Drive; Mfr. No. 1691817, 1691888 .....	1721532		6798BR
Drive; Mfr. No. 1692076 .....	1713515		6458BR
Drive; Mfr. No. 1692265 .....	1672135		6523BR
<b>1614H</b>			
Drive; Mfr. No. 1692184 .....	1713515		6458BR
Drive; Mfr. No. 1692281, 1692432, 1692809 .....	1672135		6523BR
Drive; Mfr. No. 1693058, 1693365 .....	1717932		6811BR
<b>1614VH</b>			
Drive; Mfr. No. 1692430 .....	1672135		6523BR
<b>1615G</b>			
Drive; Mfr. No. 1692289, 1692434 .....	1657044		6521BR
<b>1615H</b>			
Drive; Mfr. No. 1692530, 1692613, 1692811 .....	1672135		6523BR
Drive; Mfr. No. 1693060, 1693367, 1693596 .....	1717932		6811BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS - Continued</b>			
<b>1616H</b>			
Drive; Mfr. No. 1691819 .....	1721532		6798BR
Drive; Mfr. No. 1692075 .....	1713515		6458BR
Drive; Mfr. No. 1692285, 1692813 .....	1672135		6523BR
Drive; Mfr. No. 1693062, 1693369, 1693617 .....	1717932		6811BR
Drive; Mfr. No. 1693843 .....	1719819		6434BR
<b>1616HV</b>			
Drive; Mfr. No. 1692436 .....	1672135		6523BR
<b>1617H</b>			
Drive; Mfr. No. 1693698 .....	1719819		6434BR
<b>1618H</b>			
Drive; Mfr. No. 1693277, 1693602 .....	1717932		6811BR
<b>1714G</b>			
Drive; Mfr. No. 1692033, 1692303, 1692444 .....	1707381		6503BR
<b>1716H</b>			
Drive; Mfr. No. 1692044, 1692446, 1692633 .....	170164		6877
Drive; Mfr. No. 1692837 .....	1707381		6503BR
<b>1717H</b>			
Drive; Mfr. No. 1692839 .....	1707381		6503BR
Drive; Mfr. No. 1693395 .....	1719398		6714BR
<b>1718H</b>			
Drive; Mfr. No. 1692036, 1692448 .....	170164		6877
Drive; Mfr. No. 1692578, 1692841 .....	1707381		6503BR
Drive; Mfr. No. 1693397, 1693835 .....	1719398		6714BR
<b>1720H</b>			
Drive; W/P.S.; Mfr. No. 1693399 .....	1719398		6714BR
<b>1723H</b>			
Drive; W/P.S.; Mfr. No. 1693814 .....	1719398		6714BR
<b>1816H</b>			
Drive; Mfr. No. 1691769 .....	1656960		6811BR
<b>1817H</b>			
Drive; Mfr. No. 1691682 .....	1656960		6811BR
<b>1914H Ultima</b>			
P.T.O.; Mfr. No. 1691387 .....	1674726		ⓂA34
<b>1916H Ultima</b>			
P.T.O.; Mfr. No. 1691389 .....	1674726		ⓂA34
<b>1918H Ultima</b>			
P.T.O.; W/P.S.; Mfr. No. 1691397 .....	1674726		ⓂA34
<b>1920H</b>			
P.T.O.; Mfr. No. 1691955 .....	1674726		ⓂA34
<b>1920H Ultima</b>			
P.T.O.; Mfr. No. 1691392 .....	1674726		ⓂA34
<b>2020H</b>			
P.T.O.; W/23" Wheels; Mfr. No. 1693124 .....	1716996		Ⓜ6836
P.T.O.; W/26" Wheels; Mfr. No. 1693221 .....	1716996		Ⓜ6836
<b>2020H LC</b>			
P.T.O.; Mfr. No. 1693128 .....	1716996		Ⓜ6836
<b>2023H</b>			
P.T.O.; W/26" Wheels; Mfr. No. 1693769 .....	1716996		Ⓜ6836
<b>2024D</b>			
P.T.O.; Mfr. No. 1693130 .....	1718602		Ⓜ6834
<b>2025H</b>			
P.T.O.; Mfr. No. 1693126, 1693562 .....	1716996		Ⓜ6836
<b>3016</b>			
Drive; Mfr. No. 1691882 .....	1707345		6844
P.T.O.; Mfr. No. 1691882 .....	1705107		6939
<b>3016L</b>			
Drive; Mfr. No. 1691973 .....	1707347		6845
P.T.O.; Mfr. No. 1691973 .....	1705107		6939

ⓂTwo Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS - Continued</b>			
<b>3016S</b>			
Drive; Mfr. No. 1691970 .....	1707347		6845
P.T.O.; Mfr. No. 1691970 .....	1705107		6939
<b>3018</b>			
Drive; Mfr. No. 1691876 .....	1707344		6841
P.T.O.; Mfr. No. 1691876 .....	1705106		6937
<b>3018L</b>			
Drive; Mfr. No. 1691974 .....	1707346		6842
P.T.O.; Mfr. No. 1691974 .....	1705106		6937
<b>3018S</b>			
Drive; Mfr. No. 1691971 .....	1707346		6842
P.T.O.; Mfr. No. 1691971 .....	1705106		6937
<b>3020L</b>			
Drive; Mfr. No. 1691975 .....	1707346		6842
P.T.O.; Mfr. No. 1691975 .....	1705106		6937
<b>3020S</b>			
Drive; Mfr. No. 1691972 .....	1707346		6842
P.T.O.; Mfr. No. 1691972 .....	1705106		6937
<b>AC130</b>			
Deck Drive; W/42" Deck; W/Large Pulley .....	1732955		6710BR
Deck Drive; W/46" Deck .....	1732956		6715BR
Trans. ....	1728008		6709BR
<b>AC130 AWS</b>			
Drive .....	7101794		6474BR
Primary; W/46" Deck .....	1727869		6798BR
Secondary; W/46" Deck .....	037X66		A45
<b>B1</b>			
Arbor; W/42" Deck .....	2025364		6434BR
Belt; 2nd Type .....	2026755		6839
Belt; W/63" Belt O.C. ....	2026574		6863
Belt; W/64" Belt O.C. ....	2027145		6864
Belt; W/88" Belt O.C.; W/36" Deck .....	2027639		6988
Belt; W/96" Belt O.C.; W/36" Deck .....	2027624		6996
Cross Deck; W/32" Deck .....	2025893		6848
Cross Deck; W/48" Deck .....	2027121		6845
Drive; W/26" Belt O.C.; Mfr. No. 2025014 .....	2025436		6826
Drive; W/32" Deck .....	2025236		6956
Drive; W/35" Belt O.C.; Mfr. No. 2025014 .....	2025309		6835
Drive; W/45" Belt O.C.; Mfr. No. 2025014 .....	2025492		6945
Gear Box; W/42" Belt O.C. ....	2025641		6942
Gear Box; W/49" Belt O.C. ....	2025712		6949
Gen.; W/36" Belt O.C. ....	2025461	7360	
Gen.; W/39" Belt O.C. ....	2026869	7390	
Hydro. Lift .....	2026378		6722
Main Drive; W/32" Deck .....	2025641		6942
Mower; W/42" Deck .....	2025341		6844
Mower; W/47" Belt O.C.; W/48" Deck .....	2027581		6847
Mower; W/85" Belt O.C.; W/48" Deck .....	2027114		6885
P.T.O. ....	2025663		6835
Spindle; W/32" Deck .....	2025879		6863
Trans.; W/10" Pulley .....	2025712		6949
Trans.; W/6" Pulley .....	2025641		6942
Trans.; W/8" Pulley .....	2025492		6945
<b>B10</b>			
Arbor; W/42" Deck .....	2025364		6434BR
Belt; 2nd Type .....	2026755		6839
Belt; W/63" Belt O.C. ....	2026574		6863
Belt; W/64" Belt O.C. ....	2027145		6864
Belt; W/88" Belt O.C.; W/36" Deck .....	2027639		6988
Belt; W/96" Belt O.C.; W/36" Deck .....	2027624		6996
Cross Deck; W/32" Deck .....	2025893		6848
Cross Deck; W/48" Deck .....	2027121		6845
Drive; W/26" Belt O.C.; Mfr. No. 2025014 .....	2025436		6826
Drive; W/32" Deck .....	2025236		6956
Drive; W/35" Belt O.C.; Mfr. No. 2025014 .....	2025309		6835
Drive; W/45" Belt O.C.; Mfr. No. 2025014 .....	2025492		6945
Gear Box; W/42" Belt O.C. ....	2025641		6942

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS - Continued</b>			
<b>B10 - Continued</b>			
Gear Box; W/49" Belt O.C. ....	2025712		6949
Gen. ....	2026066	7380	
Hydro. Lift .....	2026378		6722
Main Drive; W/32" Deck .....	2025641		6942
Mower; W/42" Deck .....	2025341		6844
Mower; W/47" Belt O.C.; W/48" Deck .....	2027581		6847
Mower; W/85" Belt O.C.; W/48" Deck .....	2027114		6885
P.T.O.; Ser. No. 5000 & Before .....	2026081		6836
P.T.O.; Ser. No. 5001 & After .....	2025663		6835
Spindle; W/32" Deck .....	2025879		6863
Trans.; W/10" Pulley .....	2025712		6949
Trans.; W/6" Pulley .....	2025641		6942
Trans.; W/8" Pulley .....	2025492		6945
<b>B12</b>			
Arbor; W/42" Deck .....	2025364		6434BR
Belt; W/63" Belt O.C. ....	2026574		6863
Belt; W/64" Belt O.C. ....	2027145		6864
Belt; W/88" Belt O.C.; W/36" Deck .....	2027639		6988
Belt; W/96" Belt O.C.; W/36" Deck .....	2027624		6996
Cross Deck; W/32" Deck .....	2025893		6848
Cross Deck; W/48" Deck .....	2027121		6845
Drive; W/26" Belt O.C.; Mfr. No. 2025014 .....	2025436		6826
Drive; W/32" Deck .....	2025236		6956
Drive; W/35" Belt O.C.; Mfr. No. 2025014 .....	2025309		6835
Drive; W/45" Belt O.C.; Mfr. No. 2025014 .....	2025492		6945
Gear Box .....	2025641		6942
Gen. ....	2026869	7390	
Hydro. Lift .....	2026378		6722
Main Drive; W/32" Deck .....	2025641		6942
Mower; W/42" Deck .....	2025341		6844
Mower; W/47" Belt O.C.; W/48" Deck .....	2027581		6847
Mower; W/85" Belt O.C.; W/48" Deck .....	2027114		6885
P.T.O.; W/34" Belt O.C. ....	2027168		6834
P.T.O.; W/49" Belt O.C. ....	2025712		6949
Spindle; W/32" Deck .....	2025879		6863
<b>B110</b>			
Arbor; W/42" Deck .....	2025364		6434BR
Belt; W/61" Belt O.C. ....	2027102		6861
Belt; W/63" Belt O.C. ....	2026574		6863
Belt; W/64" Belt O.C. ....	2027145		6864
Belt; W/88" Belt O.C.; W/36" Deck .....	2027639		6988
Belt; W/96" Belt O.C.; W/36" Deck .....	2027624		6996
Cross Deck; W/32" Deck .....	2025893		6848
Cross Deck; W/48" Deck .....	2027121		6845
Drive; W/26" Belt O.C.; Mfr. No. 2025014 .....	2025436		6826
Drive; W/32" Deck .....	2025236		6956
Drive; W/35" Belt O.C.; Mfr. No. 2025014 .....	2025309		6835
Drive; W/45" Belt O.C.; Mfr. No. 2025014 .....	2025492		6945
Gear Box; W/42" Belt O.C. ....	2025641		6942
Gear Box; W/49" Belt O.C. ....	2025712		6949
Gen. ....	2026066	7380	
Hydro. Lift .....	2026378		6722
Main Drive; W/32" Deck .....	2025641		6942
Mower; W/42" Deck .....	2025341		6844
Mower; W/47" Belt O.C.; W/48" Deck .....	2027581		6847
Mower; W/85" Belt O.C.; W/48" Deck .....	2027114		6885
P.T.O.; Ser. No. 5000 & Before .....	2026081		6836
P.T.O.; Ser. No. 5001 & After .....	2025663		6835
Spindle; W/32" Deck .....	2025879		6863
Trans.; W/10" Pulley .....	2025712		6949
Trans.; W/6" Pulley .....	2025641		6942
Trans.; W/8" Pulley .....	2025492		6945
<b>B112</b>			
Arbor; W/42" Deck .....	2025364		6434BR
Belt; 2nd Type .....	2026755		6839
Belt; W/63" Belt O.C. ....	2026574		6863
Belt; W/64" Belt O.C. ....	2027145		6864
Belt; W/70" Belt O.C. ....	2027134		6870
Belt; W/88" Belt O.C.; W/36" Deck .....	2027639		6988
Belt; W/96" Belt O.C.; W/36" Deck .....	2027624		6996
Cross Deck; W/32" Deck .....	2025893		6848

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS - Continued</b>			
<b>B112 - Continued</b>			
Cross Deck; W/48" Deck	2027121		6845
Drive; W/26" Belt O.C.; Mfr. No. 2025014	2025436		6826
Drive; W/35" Belt O.C.; Mfr. No. 2025014	2025309		6835
Drive; W/45" Belt O.C.; Mfr. No. 2025014	2025492		6945
Gear Box	2025641		6942
Gen.	2026869	7390	
Hydro. Lift	2026378		6722
Main Drive; W/32" Deck	2025641		6942
Mower; W/42" Deck	2025893		6848
Mower; W/47" Belt O.C.; W/48" Deck	2027581		6847
Mower; W/85" Belt O.C.; W/48" Deck	2027114		6885
Spindle; W/32" Deck	2025879		6863
<b>B206</b>			
Arbor; W/42" Deck	2025364		6434BR
Belt; W/39" Belt O.C.	2026755		6839
Belt; W/63" Belt O.C.	2026574		6863
Belt; W/64" Belt O.C.	2027145		6864
Belt; W/88" Belt O.C.; W/36" Deck	2027639		6988
Belt; W/96" Belt O.C.; W/36" Deck	2027624		6996
Blade; W/36" Deck	1601520		6870
Blade; W/73" Belt O.C.	1602157	2730	6873
Cross Deck; W/32" Deck	2025893		6848
Cross Deck; W/48" Deck	2027121		6845
Drive; W/26" Belt O.C.; Mfr. No. 2025014	2025436		6826
Drive; W/32" Deck	2025236		6956
Drive; W/35" Belt O.C.; Mfr. No. 2025014	2025309		6835
Drive; W/45" Belt O.C.; Mfr. No. 2025014	2025492		6945
Main Drive; W/32" Deck	2025641		6942
Mower; W/42" Deck	2025341		6844
Mower; W/47" Belt O.C.; W/48" Deck	2027581		6847
Mower; W/85" Belt O.C.; W/48" Deck	2027114		6885
Mower Drive; W/26" Deck	1602157		6873
Spindle; W/32" Deck	2025879		6863
Trans.	1601405		6840
<b>B207; B208</b>			
Arbor; W/42" Deck	2025364		6434BR
Belt; W/39" Belt O.C.	2026755		6839
Belt; W/63" Belt O.C.	2026574		6863
Belt; W/64" Belt O.C.	2027145		6864
Belt; W/88" Belt O.C.; W/36" Deck	2027639		6988
Belt; W/96" Belt O.C.; W/36" Deck	2027624		6996
Blade; W/36" Deck	1601520		6870
Countershaft To Trans.	1601672		6799BR
Cross Deck; W/32" Deck	2025893		6848
Cross Deck; W/48" Deck	2027121		6845
Drive; W/26" Belt O.C.; Mfr. No. 2025014	2025436		6826
Drive; W/32" Deck	2025236		6956
Drive; W/35" Belt O.C.; Mfr. No. 2025014	2025309		6835
Drive; W/45" Belt O.C.; Mfr. No. 2025014	2025492		6945
Eng. To Countershaft	1601405		6840
Eng. To Deck	1601524		6878
Gen.	1601238	7340	
Main Drive; W/32" Deck	2025641		6942
Mower; W/42" Deck	2025341		6844
Mower; W/47" Belt O.C.; W/48" Deck	2027581		6847
Mower; W/85" Belt O.C.; W/48" Deck	2027114		6885
Mower Drive; W/26" Deck	1602157		6873
Spindle; W/32" Deck	2025879		6863
<b>B210; B212</b>			
Arbor; W/42" Deck	2025364		6434BR
Belt; W/39" Belt O.C.	2026755		6839
Belt; W/63" Belt O.C.	2026574		6863
Belt; W/64" Belt O.C.	2027145		6864
Belt; W/88" Belt O.C.; W/36" Deck	2027639		6988
Belt; W/96" Belt O.C.; W/36" Deck	2027624		6996
Blade; W/36" Deck	1601520		6870
Cross Deck; W/32" Deck	2025893		6848
Cross Deck; W/48" Deck	2027121		6845

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS - Continued</b>			
<b>B210; B212 - Continued</b>			
Drive; W/26" Belt O.C.; Mfr. No. 2025014	2025436		6826
Drive; W/32" Deck	2025236		6956
Drive; W/35" Belt O.C.; Mfr. No. 2025014	2025309		6835
Drive; W/45" Belt O.C.; Mfr. No. 2025014	2025492		6945
Gen.	2026869	7390	
Hydro. Lift	2026378		6722
Main Drive; W/32" Deck	2025641		6942
Mower; W/42" Deck	2025341		6844
Mower; W/47" Belt O.C.; W/48" Deck	2027581		6847
Mower; W/85" Belt O.C.; W/48" Deck	2027114		6885
Mower Drive; W/26" Deck	1602157		6873
P.T.O.	2027709		6829
Spindle; W/32" Deck	2025879		6863
<b>Big 10</b>			
Arbor; W/42" Deck	2025364		6434BR
Belt; 2nd Type	2026755		6839
Belt; W/63" Belt O.C.	2026574		6863
Belt; W/64" Belt O.C.	2027145		6864
Belt; W/88" Belt O.C.; W/36" Deck	2027639		6988
Belt; W/96" Belt O.C.; W/36" Deck	2027624		6996
Cross Deck; W/32" Deck	2025893		6848
Cross Deck; W/48" Deck	2027121		6845
Drive; W/26" Belt O.C.; Mfr. No. 2025014	2025436		6826
Drive; W/32" Deck	2025236		6956
Drive; W/35" Belt O.C.; Mfr. No. 2025014	2025309		6835
Drive; W/45" Belt O.C.; Mfr. No. 2025014	2025492		6945
Gear Box; W/42" Belt O.C.	2025641		6942
Gear Box; W/49" Belt O.C.	2025712		6949
Gen.; W/36" Belt O.C.	2025461	7360	
Gen.; W/39" Belt O.C.	2026869	7390	
Hydro. Lift	2026378		6722
Main Drive; W/32" Deck	2025641		6942
Mower; W/42" Deck	2025341		6844
Mower; W/47" Belt O.C.; W/48" Deck	2027581		6847
Mower; W/85" Belt O.C.; W/48" Deck	2027114		6885
P.T.O.	2025663		6835
Spindle; W/32" Deck	2025879		6863
Trans.; W/10" Pulley	2025712		6949
Trans.; W/6" Pulley	2025641		6942
Trans.; W/8" Pulley	2025492		6945
<b>Express</b>			
Drive; W/14.5 H.P. Eng.; Mfr. No. 1693452		1665450	6627BR
Drive; W/15 H.P. Eng.; Mfr. No. 1693458		1717397	6798BR
Drive; W/17 H.P. Eng.; Mfr. No. 1693525		1717397	6798BR
<b>HB112; HB212</b>			
Arbor; W/42" Deck	2025364		6434BR
Belt; W/63" Belt O.C.	2026574		6863
Belt; W/64" Belt O.C.	2027145		6864
Belt; W/88" Belt O.C.; W/36" Deck	2027639		6988
Belt; W/96" Belt O.C.; W/36" Deck	2027624		6996
Clutch	2027581		6847
Cross Deck; W/32" Deck	2025893		6848
Cross Deck; W/48" Deck	2027121		6845
Drive; W/26" Belt O.C.; Mfr. No. 2025014	2025436		6826
Drive; W/32" Deck	2025236		6956
Drive; W/35" Belt O.C.; Mfr. No. 2025014	2025309		6835
Drive; W/45" Belt O.C.; Mfr. No. 2025014	2025492		6945
Gen.	2026869	7390	
Hydro. Lift	2026378		6722
Main Drive; W/32" Deck	2025641		6942
Mower; W/42" Deck	2025341		6844
Mower; W/47" Belt O.C.; W/48" Deck	2027581		6847
Mower; W/85" Belt O.C.; W/48" Deck	2027114		6885
P.T.O.	2027709		6829
Rear P.T.O.	2025712		6949





Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS - Continued</b>				<b>AMERICAN HARDWARE - Continued</b>			
<b>HB112; HB212 - Continued</b>				<b>144-761</b>			
Spindle; W/32" Deck .....	2025879		6863	Drive .....	7540182	3810	6981
<b>Homesteader 6; Homesteader 7</b>				Gen. ....	7540134	7330	
Blade; W/78" Belt O.C. ....	1601524		6878	<b>144-960</b>			
Blade; W/83" Belt O.C. ....	1604406		6444BR	Gen. ....	7540139	7380	
Trans. ....	1607051		6870	P.T.O. ....	7540165		6834
<b>Homesteader 8</b>				<b>144-990</b>			
Arbor; W/36" Deck .....	1602157		6873	P.T.O. ....	7540165		6834
Belt; W/82" Belt O.C. ....	2025364		6434BR	<b>145-960; 145-990</b>			
Belt; W/96" Belt O.C. ....	2027624		6996	Gen. ....	7540139	7380	
Blade .....	1602157	2730	6873	P.T.O. ....	7540165		6834
Gen. ....	1601238	7340		Trans. ....	7540124		6857
Mower; Ser. No. 26601001 & After;				<b>09405</b>			
W/36" Deck .....	2029715		6879	Belt; W/40" Belt O.C. ....	7540244		6840
P.T.O. ....	1601524		6878	Belt; W/59" Belt O.C. ....	7540245		6859
Trans. ....	2028035		6775BR	<b>14925</b>			
<b>Scamp 5</b>				<b>14925</b>			
Belt; W/24" Deck .....	2025893	2480	6848	Blade .....	7540151		6967
Belt; W/26" Deck .....	2029223	2440	6844	Deck .....	7540138	3500	6950
Trans. ....	2028241		6831	Traction .....	7540136		6931
<b>Scamp 8</b>				<b>14938</b>			
Drive .....	2029660		6862	Blade .....	7540145		6488BR
P.T.O. To Mower .....	2029582		A133	Trans. ....	7540226		6551BR
<b>ZT</b>				<b>20508</b>			
Drive; W/14 H.P. Eng.; Mfr. No.				Drive .....	37X38		6425BR
1693469 .....	1719381		6838	<b>21866</b>			
Drive; W/16 H.P. Eng.; Mfr. No.				Blade .....	7540184		6852
1693475 .....	1719381		6838	Deck .....	7540180		6510BR
Drive; W/18 H.P. Eng.; Mfr. No.				Gen. ....	7540134	7330	
1693232 .....	1719381		6838	Trans. ....	7540182	3810	6981
<b>AMERICAN HARDWARE</b>				<b>26861</b>			
<b>127-364</b>				<b>26861</b>			
Deck .....	7540342		6866	Blade .....	37X34		6877
<b>130-460; 130-470</b>				Drive .....	37X27		6434BR
Blade .....	7540118		6963	<b>37277</b>			
Trans. ....	7540937	3590	6959	Belt; W/39" Belt O.C. ....	7540271		6557BR
<b>131-480</b>				Trans. ....	7540281		6405BR
Blade .....	7540145		6488BR	<b>39510</b>			
Drive; W/31" Belt O.C. ....	7540136		6931	Blade .....	7540167		6964
Drive; W/52" Belt O.C. ....	7540147	3520	6952	Trans. ....	7540198		6451BR
<b>137-322; 137-332</b>				<b>39511</b>			
Deck .....	7540342		6866	Blade .....	7540145		6488BR
<b>137-504</b>				Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/35" Belt O.C. ....	7540241		6494BR	Drive; W/65" Belt O.C. ....	7540191		6865
Drive; W/38" Belt O.C. ....	7540240		6511BR	<b>39512</b>			
<b>141-660; 141-690; 142-669</b>				Blade; W/51" Belt O.C. ....	7540188		6951
Gen. ....	7540134	7330		Blade; W/52" Belt O.C. ....	7540264		6639BR
Trans. ....	7540112	3800	6980	Trans.; W/30" Belt O.C. ....	7540249		6930
<b>142-760</b>				Trans.; W/35" Belt O.C. ....	7540101		6517BR
Gen. ....	7540139	7380		<b>41420</b>			
P.T.O. ....	7540165		6834	Belt; W/69" Belt O.C. ....	7540145		6488BR
<b>142-990</b>				Trans. ....	7540281		6405BR
P.T.O. ....	7540165		6834	<b>41640</b>			
<b>143-660; 143-760</b>				Drive .....	7540264		6639BR
Blade .....	7540184		6852	<b>41642</b>			
Deck .....	7540180		6510BR	Eng. To Deck .....	7540264		6639BR
Gen. ....	7540134	7330		Primary Variator .....	7540241		6494BR
Trans. ....	7540182	3810	6981	Secondary Variator .....	7540240		6511BR
<b>143-960</b>				<b>42387</b>			
Gen. ....	7540139	7380		Gen. ....	7540134	7330	
P.T.O. ....	7540165		6834	Trans. ....	7540112	3800	6980
<b>143-990</b>				<b>Belmont</b>			
P.T.O. ....	7540165		6834	P.T.O. ....	7540165		6834
<b>144-672</b>				Trans. ....	7540124		6857
Blade .....	7540184		6852	<b>Bradley 134-445</b>			
Deck .....	7540180		6510BR	Blade .....	7540178	3820	6982
Gen. ....	7540134	7330		Drive .....	7540185		6849
Trans. ....	7540182	3810	6981	<b>Denison 133-485; Denison 134-485</b>			
				Trans. ....	7540127		6966

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN HARDWARE - Continued</b>			
<b>Jamestown 134-400</b>			
Blade .....	7540188		6951
Drive .....	7540101		6517BR
<b>Jefferson 132-360</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>Kingwood</b>		7355	
Gen. ....	7540169		6834
P.T.O. ....	7540165		
<b>Lagrange 134-495</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>Madison 132-485</b>		3500	
Drive .....	7540138		6950
Trans. ....	7540136		6931
<b>Marquette 133-480</b>			
Trans. ....	7540127		6966
<b>Millbrook 130-430; Millbrook 131-435; Millbrook 132-435</b>			
Deck .....	7540127		6966
Drive .....	7540135		6925
Trans. ....	7540136		6931
<b>Oakwood 134-395</b>		2630	
Drive .....	7540164		6863
<b>Parkhill 132-480</b>		3500	
Drive .....	7540138		6950
Trans. ....	7540136		6931
<b>Servistar 130-400</b>			
Blade .....	7540188		6951
Drive .....	7540101		6517BR
<b>Servistar 130-465</b>		3500	
Blade .....	7540151		6967
Deck .....	7540138		6950
Traction .....	7540136		6931
<b>Servistar 130-497</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6882
<b>Servistar 130-780</b>			
Deck; W/Optional 44" Deck .....	7540230		6755BR
Drive .....	7540245		6859
Transaxle .....	7540255		6837
<b>Servistar 130-796</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>Servistar 15331; Servistar 15831</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>Springhill</b>			
Trans. ....	7540182		6981
<b>Whitehall 130-415; Whitehall 132-418; Whitehall 133-420</b>		3520	
Deck .....	7540147		6952
Drive .....	7540135		6925
Trans. ....	7540136		6931
<b>Williams 133-380; Williams 134-380</b>		3500	
Blade; W/25" Deck .....	7540138		6950
Drive .....	7540164	2630	6863
<b>AMERICAN HARDWARE SERVISTAR</b>			
<b>14925</b>			
Blade .....	7540151	3670	6967
Eng. To Variator .....	7540138	3500	6950
Variator To Trans. ....	7540136	3310	6931
<b>15331</b>		3670	
Blade .....	7540151		6967
Trans. ....	7540181		7014BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD.</b>			
<b>1A1A1A; 1C1A7A</b>			
Deck .....	131264		6458BR
<b>1D2A3A; 1E2A9A</b>		131290	
Deck .....			6459BR
<b>1H2A9A</b>			
Deck .....	131290		6459BR
Ground Drive .....	126520X		6459BR
<b>2C3B1A; 2C3B1B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>2D3B3B; 2D3B3C</b>			
Deck .....	126520X		6459BR
Ground Drive .....	138255		6758BR
<b>2D3B3D</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>2E3B3A</b>			
Deck .....	131290		6459BR
<b>2E3B3B</b>			
Deck .....	126520X		6459BR
Ground Drive .....	138255		6758BR
<b>2E3B3C; 2E3B3D</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>2H4B3A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>2H4B3B</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>2H4B3C; 2H4B3E</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>2H4B6B; 2H4B6C</b>			
Deck .....	144200		6463BR
<b>2H4B38A</b>			
Deck .....	130969		6457BR
<b>2H4D3A; 2H4D3B; 2H4D3C</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>2K4B3A; 2K4B9A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>2P4B9A</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>2P4B9B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>2P4C3A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>2Q4B9A; 2Q4B9B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>4P6D9A</b>			
Deck .....	131290		6459BR
<b>6A1A1E; 6C1A7E; 6H1A9D</b>			
Deck .....	131264		6458BR
<b>7H4B6A</b>			
Deck .....	144200		6463BR
<b>7H4B8A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>11HP92</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>12HP-97CM</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>13HP92</b>			
Deck .....	165555		6579BR
<b>850-6552</b>			
Deck .....	130969		6457BR
Drive .....	131006		6898
<b>917.252500; 917.252520; 917.252521;</b>			
<b>917.252580</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>3363</b>			
Deck .....	124293X		6880
Ground Drive .....	126520X		6459BR
<b>3380-14</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>3381E94</b>			
Deck .....	106085X		6672BR
<b>3383-14</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>3420-24; 3420-34</b>			
Deck .....	130969		6457BR
Drive .....	131006		6898
<b>3420-44</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>3420-54; 3420-64; 3420-74</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>3420-74A</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>3420-74B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>3420-84</b>			
Deck .....	144200		6463BR
<b>3421H-74</b>			
Deck .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>3421H-74A</b>			
Ground Drive .....	156971		6558BR
<b>3421H-74B</b>			
Deck .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>3441E94</b>			
Deck .....	106085X		6672BR
<b>4180-24; 4180-24B; 4180-34</b>			
Deck .....	106085X		6672BR
Ground Drive .....	123796X		6432BR
<b>4180-44; 4180-54; 4180-64; 4181-44</b>			
Ground Drive .....	123796X		6432BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>4186-64</b>			
Primary .....	148763		6702BR
<b>4200-14; 4200-34</b>			
Ground Drive .....	110883X		6899
Primary .....	110884X		6714BR
Secondary .....	3703J		A98

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>4200-44; 4200V-44; 4200V-54</b>			
Ground Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>4220-74; 4220-84</b>			
Ground Drive .....	137153		6798BR
<b>4221-84; 4221H-74</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>6421H-74; 7124A89</b>			
Deck .....	144200		6463BR
<b>7143A89</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>7177A89; 7187A89</b>			
Deck .....	144200		6463BR
<b>8927B</b>			
Deck .....	130969		6457BR
Drive .....	131006		6898
<b>9149A89; 9149B89; 9191A89</b>			
Deck .....	144200		6463BR
<b>95189</b>			
Deck .....	130969		6457BR
Drive .....	131006		6898
<b>259720; 259721; 259722; 259723; 259724;</b>			
<b>270450</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>270451</b>			
Deck .....	144200		6463BR
<b>271150</b>			
Deck .....	144200		6463BR
Ground Drive .....	160855		6432BR
<b>271470; 271471; 271490; 271491</b>			
Deck .....	144200		6463BR
<b>279370</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>421170; 421171; 421172</b>			
Deck .....	144200		6463BR
<b>421360C; 421361</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>425170; 425171</b>			
Deck .....	131290		6459BR
Ground Drive .....	130801		6758BR
<b>425180; 425181</b>			
Ground Drive .....	123796X		6432BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>440500; 440501</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>446400</b>			
Deck .....	144200		6463BR
<b>951890; 951891</b>			
Deck .....	130969		6457BR
Drive .....	131006		6898
<b>951941</b>			
Ground Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>951942; 951942C; 951943; 951944</b>			
Ground Drive .....	137153		6798BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>AB13107B</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AK125H42B</b>			
Deck .....	144200		<b>6463BR</b>
<b>AK12542C</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AK12542D</b>			
Deck .....	144959		<b>6758BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AP12R38A</b>			
Deck .....	126520X		<b>6459BR</b>
Ground Drive .....	124525X		<b>6889</b>
<b>AP125HR38A</b>			
Deck .....	126520X		<b>6459BR</b>
<b>AY12B36C</b>			
Deck .....	131264		<b>6458BR</b>
Ground Drive .....	126520X		<b>6459BR</b>
<b>AY1236A; AY1236B</b>			
Deck .....	131264		<b>6458BR</b>
<b>AY1236E</b>			
Deck .....	131264		<b>6458BR</b>
Ground Drive .....	126520X		<b>6459BR</b>
<b>AY12536A; AY12536B</b>			
Deck .....	131264		<b>6458BR</b>
<b>AYF1236C</b>			
Deck .....	131264		<b>6458BR</b>
Ground Drive .....	126520X		<b>6459BR</b>
<b>AYP1124A69; AYP1143A69; AYP1184A69</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7122A29; AYP7122B29</b>			
Deck .....	131290		<b>6459BR</b>
<b>AYP7124A49</b>			
Deck .....	130969		<b>6457BR</b>
Ground Drive .....	138255		<b>6758BR</b>
<b>AYP7124A59; AYP7124A69; AYP7124A79; AYP7124B59; AYP7124B79</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7124C49</b>			
Deck .....	140067		<b>6551BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7134A99</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7143A49</b>			
Deck .....	130969		<b>6457BR</b>
Ground Drive .....	138255		<b>6758BR</b>
<b>AYP7143A59; AYP7143A69; AYP7143A79; AYP7143A99</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7143B49</b>			
Deck .....	130969		<b>6457BR</b>
Ground Drive .....	138255		<b>6758BR</b>
<b>AYP7143B59</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7143B79</b>			
Deck .....	144959		<b>6758BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7143B89</b>			
Deck .....	144200		<b>6463BR</b>

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>AYP7143C49</b>			
Deck .....	140067		<b>6551BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7143C79</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7147A29; AYP7147B29</b>			
Deck .....	130969		<b>6457BR</b>
Ground Drive .....	138255		<b>6758BR</b>
<b>AYP7148A49</b>			
Deck .....	140067		<b>6551BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7157A79</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7157B79</b>			
Deck .....	144959		<b>6758BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7158A49</b>			
Deck .....	140067		<b>6551BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7159A59; AYP7159A69</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7167A29; AYP7167A39</b>			
Deck .....	130969		<b>6457BR</b>
Drive .....	131006		<b>6898</b>
<b>AYP7167A59; AYP7167A69; AYP7167A79</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7167B29</b>			
Deck .....	130969		<b>6457BR</b>
Drive .....	131006		<b>6898</b>
<b>AYP7167B79</b>			
Deck .....	144959		<b>6758BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7167C79; AYP7169A99; AYP7169B99; AYP7178B99; AYP7178C99</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP7183A49</b>			
Deck .....	130969		<b>6457BR</b>
Ground Drive .....	138255		<b>6758BR</b>
<b>AYP7184A59; AYP7184A69; AYP7184B69; AYP7187A99</b>			
Deck .....	144200		<b>6463BR</b>
Ground Drive .....	130801		<b>6758BR</b>
<b>AYP8186A29</b>			
Deck .....	106085X		<b>6672BR</b>
Ground Drive .....	123796X		<b>6432BR</b>
<b>AYP8186A49; AYP8186A59</b>			
Ground Drive .....	123796X		<b>6432BR</b>
Primary .....	131264		<b>6458BR</b>
Secondary .....	131290		<b>6459BR</b>
<b>AYP8186A79; AYP8186B79</b>			
Ground Drive .....	123796X		<b>6432BR</b>
Primary .....	158818		<b>6444BR</b>
Secondary .....	144959		<b>6758BR</b>
<b>AYP8188A69</b>			
Ground Drive .....	137153		<b>6798BR</b>
Primary .....	148763		<b>6702BR</b>
<b>AYP8188A79; AYP8188A89; AYP8188B89</b>			
Ground Drive .....	137153		<b>6798BR</b>
<b>AYP8196A89; AYP8196A99; AYP8196B89</b>			
Ground Drive .....	163817		<b>6432BR</b>
Primary .....	158818		<b>6444BR</b>
Secondary .....	144959		<b>6758BR</b>



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>				<b>AMERICAN YARD PROD. - Continued</b>			
<b>AYP8209A49</b>				<b>CH1238A</b>			
Ground Drive .....	137153		6798BR	Deck .....	131290		6459BR
Primary .....	139573		6798BR	<b>CH1238B</b>			
Secondary .....	138255		6758BR	Deck .....	131290		6459BR
<b>AYP8209A59; AYP8209A79; AYP8209A89;</b>				Ground Drive .....	130801		6758BR
<b>AYP8209A99; AYP8209B89</b>				<b>CH14542A; CH14542B</b>			
Ground Drive .....	137153		6798BR	Deck .....	144200		6463BR
<b>AYP8228A49</b>				Ground Drive .....	130801		6758BR
Ground Drive .....	140218		6811BR	<b>CHD145H42A</b>			
Primary .....	139573		6798BR	Deck .....	144200		6463BR
Secondary .....	138255		6758BR	Ground Drive .....	156971		6558BR
<b>AYP8228A59; AYP8228A69; AYP8228A79;</b>				<b>CHD145H42C; CHD145H42D</b>			
<b>AYP8228A89; AYP8228B89; AYP8248A99</b>				Deck .....	144200		6463BR
Ground Drive .....	140218		6811BR	<b>CHD12538A; CHD12538B</b>			
Primary .....	139573		6798BR	Deck .....	144200		6463BR
Secondary .....	144959		6758BR	Ground Drive .....	130801		6758BR
<b>AYP9120A29</b>				<b>CHD12538C</b>			
Deck .....	131264		6458BR	Deck .....	144200		6463BR
<b>AYP9120A59; AYP9120B49; AYP9120B59</b>				<b>CHD12538D; CHD14542A; CLT4216B;</b>			
Deck .....	126520X		6459BR	<b>CM1238A</b>			
Ground Drive .....	124525X		6889	Deck .....	144200		6463BR
<b>AYP9128A29; AYP9128B29</b>				Ground Drive .....	130801		6758BR
Deck .....	131290		6459BR	<b>CP10L36A</b>			
<b>AYP9149A59; AYP9149A69</b>				Deck .....	131264		6458BR
Deck .....	144200		6463BR	<b>CP12TR38A</b>			
<b>AYP9149A79; AYP9149B79; AYP9149C79;</b>				Deck .....	126520X		6459BR
<b>AYP9158A79</b>				Ground Drive .....	124525X		6889
Deck .....	144200		6463BR	<b>CP18H42A</b>			
Ground Drive .....	156971		6558BR	Deck .....	144200		6463BR
<b>AYP9158B79</b>				<b>CP125T38A</b>			
Ground Drive .....	156971		6558BR	Deck .....	126520X		6459BR
<b>AYP9159A59</b>				Ground Drive .....	138255		6758BR
Deck .....	144200		6463BR	<b>CP1238A</b>			
<b>AYP9159A69</b>				Deck .....	131290		6459BR
Deck .....	144200		6463BR	<b>CP1442A</b>			
Ground Drive .....	140294		6434BR	Deck .....	130969		6457BR
<b>AYP9159B59; AYP9167A59; AYP9167A69</b>				Ground Drive .....	138255		6758BR
Deck .....	144200		6463BR	<b>CP1442B</b>			
<b>AYP9167A79; AYP9167B79; AYP9167C79;</b>				Deck .....	140067		6551BR
<b>AYP9167D79</b>				Ground Drive .....	130801		6758BR
Deck .....	144200		6463BR	<b>CP1642A</b>			
Ground Drive .....	156971		6558BR	Deck .....	144200		6463BR
<b>AYP9169A99; AYP9177A89; AYP9177B89;</b>				Ground Drive .....	130801		6758BR
<b>AYP9178A99; AYP9178B99</b>				<b>CP1842A; CP1842B; CP1842C</b>			
Deck .....	144200		6463BR	Deck .....	130969		6457BR
<b>AYP9182A79; AYP9182B79; AYP9182C79</b>				Drive .....	131006		6898
Deck .....	144200		6463BR	<b>CP1842D</b>			
Ground Drive .....	156971		6558BR	Deck .....	140067		6551BR
<b>AYP9187A89; AYP9187A99</b>				Ground Drive .....	130801		6758BR
Deck .....	144200		6463BR	<b>CP1844C</b>			
<b>AYP9187B89</b>				Deck .....	131290		6459BR
Deck .....	144200		6463BR	<b>CP2050B</b>			
Ground Drive .....	140294		6434BR	Ground Drive .....	137153		6798BR
<b>AYP9191A99; AYP9191B89</b>				Primary .....	139573		6798BR
Deck .....	144200		6463BR	Secondary .....	138255		6758BR
<b>AYP9209A99</b>				<b>CP10910A</b>			
Primary .....	148763		6702BR	Deck .....	131264		6458BR
<b>BM125M92EJA; BM155H92EJA</b>				<b>CP12542A</b>			
Deck .....	165555		6579BR	Deck .....	130969		6457BR
<b>CB13H36A</b>				Ground Drive .....	138255		6758BR
Deck .....	131264		6458BR	<b>CP12542LTA</b>			
<b>CB15H42B</b>				Deck .....	140067		6551BR
Deck .....	144200		6463BR	Ground Drive .....	130801		6758BR
<b>CB1136C; CH1136A; CH1136B</b>				<b>CP14542A; CP14542B; CP14542C</b>			
Deck .....	131264		6458BR	Deck .....	144200		6463BR

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>CP14542A; CP14542B; CP14542C – Continued</b>			
Ground Drive .....	130801		6758BR
<b>CS16H42A</b>			
Ground Drive .....	156971		6558BR
<b>CS16H42B</b>			
Deck .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>CS12538A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>CSGT18546A</b>			
Ground Drive .....	123796X		6432BR
Primary .....	158818		6444BR
Secondary .....	144959		6758BR
<b>CT10L36A; CT10L36B; CT10L36C</b>			
Deck .....	131264		6458BR
<b>CT12T38A; CT12T38B; CT12T38C</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>CT12T38D</b>			
Deck .....	144200		6463BR
<b>CT12T38E</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>CT20V50A; CT20V50B; CT20V50C</b>			
Ground Drive .....	137153		6798BR
<b>CT125R38A</b>			
Deck .....	131290		6459BR
Ground Drive .....	126520X		6459BR
<b>CT125R38B</b>			
Deck .....	131290		6459BR
<b>CT1138A</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>CT1138B; CT1138C</b>			
Deck .....	131290		6459BR
<b>CT1236C</b>			
Deck .....	131264		6458BR
<b>CT1236D; CT1236E</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>CT1238A</b>			
Deck .....	131290		6459BR
<b>CT1238B</b>			
Deck .....	126520X		6459BR
Ground Drive .....	138255		6758BR
<b>CT1238C; CT1238D</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>CT1442A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>CT1642A</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>CT1842A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>CT1844A; CT1844E</b>			
Deck .....	106085X		6672BR
Drive .....	123554X		6894
<b>CT1844F</b>			
Deck .....	106085X		6672BR
Drive .....	123796X		6432BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>CT1844G; CT1844H; CT1844J</b>			
Ground Drive .....	123796X		6432BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>CT2050B</b>			
Ground Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>CT2050C</b>			
Ground Drive .....	137153		6798BR
<b>CT12538A</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>CT12538B</b>			
Deck .....	131290		6459BR
<b>CT12542A; CT12542B; CT12542C; CT12542D</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>CT12542E</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>CT12542F; CT12542G; CT12542H; CT12542J;</b>			
<b>CT12542K</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>CT12542L</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>CT12542M; CT12542N; CT12542P</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>CT12542R</b>			
Deck .....	144200		6463BR
<b>CT12542S</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>CT14538A</b>			
Deck .....	126520X		6459BR
Ground Drive .....	138255		6758BR
<b>CT14538B; CT14538C; CT14538D; CT14542A;</b>			
<b>CT14542B; CT14542C</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>CT14542D</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>CT14542E</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>CT14542F</b>			
Deck .....	144200		6463BR
<b>CT14542G; CT14542H</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>CT18544A; CT18544B</b>			
Ground Drive .....	123796X		6432BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>CTB1442A</b>			
Deck .....	130969		6457BR
Drive .....	131006		6898
<b>CTB12538B</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>CTH1642A; CTH1642B; CTH1642C</b>			
Deck .....	144200		6463BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>CTH1642D; CTH1642E</b>			
Deck .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>CTH14542A; CTH14542B; CTH14542C</b>			
Deck .....	144200		6463BR
<b>CTH14542D; CTH14542E</b>			
Ground Drive .....	156971		6558BR
<b>CTH14542F</b>			
Deck .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>CTH14542G; CTH14542H; CTH14542J; CTH14542K; CTH16542A; CTH16542B</b>			
Deck .....	144200		6463BR
<b>CTL14R38A</b>			
Deck .....	126520X		6459BR
Ground Drive .....	124525X		6889
<b>CTL125R38A</b>			
Deck .....	131290		6459BR
<b>CTW14542A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>DE11B36A; DE11B36B; DE11B36C; DE11B92A</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>DE16H36RBA; DE16HT36RBA; DE145H36RBA; DE145H36RBC</b>			
Deck .....	165555		6579BR
<b>DE1136A; DE1136B; DE1136C</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>DE1236RBA; DE1236RBB</b>			
Deck .....	165555		6579BR
<b>DE1242A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>DE1336RBA; DE14536RBA</b>			
Deck .....	165555		6579BR
<b>DPR20H46STA; DPR20H46STB; DPR22H46STA; DPR22H46STB</b>			
Primary .....	148763		6702BR
<b>EHP1642A</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>EN11TB36A</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>EN145RBA; EN145RBHA</b>			
Deck .....	165555		6579BR
<b>GM1442A</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>GM12538A</b>			
Deck .....	131290		6459BR
<b>GP1236A</b>			
Deck .....	131264		6458BR
<b>GPT13B36C</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>GS12536A</b>			
Deck .....	165555		6579BR
<b>GS14536HA</b>			
Deck .....	165555		6579BR
Drive .....	165632		6928BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>GT2500AR</b>			
Deck .....	106085X		6672BR
Drive .....	123554X		6894
<b>GT4418A; GT4418B; GT4418C; GT44185A</b>			
Deck .....	131290		6459BR
<b>HD2G4E8A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>HD2G4E8B</b>			
Deck Drive .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>HD3K4E9A; HD3L4E9A; HD3L4E9B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>HD3Q4E6A; HD3Q4E6B</b>			
Deck Drive .....	144200		6463BR
<b>HD3Q4E9A; HD3Q4E9B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>HD19H42A</b>			
Deck .....	144200		6463BR
<b>HD145H42A</b>			
Deck .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>HD145H42B</b>			
Ground Drive .....	156971		6558BR
<b>HD145H42D</b>			
Deck .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>HD145H42E</b>			
Deck .....	144200		6463BR
<b>HD145H42F</b>			
Deck .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>HD145H42G; HD145H42H; HD145H42J</b>			
Deck .....	144200		6463BR
<b>HD185H46A; HD185H46B</b>			
Primary .....	158818		6444BR
Secondary .....	144959		6758BR
<b>HD1442A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>HD2044A</b>			
Ground Drive .....	123796X		6432BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>HD12538A; HD12538B; HD12538C; HD12538D; HD12538E</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>HD12538F</b>			
Deck .....	144200		6463BR
<b>HD12538G; HD12538H; HD12538J; HD14542A; HD14542B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>HDC145H42A; HDC145H42B; HDC145H42C; HDC145H42D</b>			
Deck Drive .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>HDC185H46A; HDC185H46B</b>			
Primary .....	158818		6444BR
Secondary .....	144959		6758BR

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
HDC12538A; HDC12538B; HDC12538C; HDT1338A; HDT1542A			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>HN2050A</b>			
Ground Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>L2400AR</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>LC20VH50A</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>LM145H42A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>LT110CR</b>			
Deck .....	106085X		6672BR
Drive .....	130969		6457BR
<b>LT110DR; LT110FR; LT110GR; LT120AR; LT120CR</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>LT4216A</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>LT4216B; LT4216C; LT4216D; LT4216E; LT4216F</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>LT4218A; LT4218B</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>LT4218C; LT4218D</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>LTH120AR</b>			
Deck .....	106085X		6672BR
Drive .....	120418X		6880
<b>LTT120AR</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>M14542A; M14542B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>MBA15T107A</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>MBA1392A; MBA1392B</b>			
Deck .....	165555		6579BR
<b>MBA16107A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>MBA16107B</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>MT13H36D</b>			
Deck .....	131264		6458BR
<b>MT1336D</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>MT12536RBA</b>			
Deck .....	165555		6579BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>MT15536RBHA</b>			
Deck .....	165555		6579BR
Drive .....	165632		6928BR
<b>PC1338A; PC1538A; PC1538B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>PC1538C</b>			
Deck .....	144200		6463BR
Ground Drive .....	138255		6758BR
<b>PC1844A</b>			
Deck .....	106085X		6672BR
Drive .....	123554X		6894
<b>PC12538A</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>PC14542A; PC14542B; PC14542C; PC14542D; PD1842STA; PD2042STA</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>PDGT26H48A; PDGT26H48B</b>			
Ground Drive .....	161597		6551BR
<b>PO1538A; PO1538B; PO1538C</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>PO1742STA; PO1842STA; PO14542A; PO14542B; PO14542C; PO14542D; PO14542E; PO14542F; PO16542A</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>POGT20H48STA</b>			
Drive .....	161741		6572BR
<b>PP16H46; PP16H46A; PP16H46B</b>			
Ground Drive .....	156971		6558BR
<b>PP18H46; PP18H46A; PP18H46B</b>			
Ground Drive .....	161597		6551BR
<b>PP20H46</b>			
Primary .....	148763		6702BR
<b>PP22H50; PP22H50A; PP22H50B; PP24H50A; PP24H50B</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>PP145H42; PP145H42A; PP145H42B</b>			
Deck Drive .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>PP165H42; PP165H42A</b>			
Deck Drive .....	144200		6463BR
Ground Drive .....	161597		6551BR
<b>PP1338; PP1338A; PP1338B; PP1338D</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>PP1846; PP1846A</b>			
Ground Drive .....	137153		6798BR
<b>PP11536; PP11536A</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>PPR16H42STA; PPR17H42STA; PPR17H42STB</b>			
Deck Drive .....	144200		6463BR
<b>PPR20H46STA</b>			
Primary .....	148763		6702BR
<b>PPR1742STA; PPR1742STB</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>PPR2042STA; PPR2042STB</b>			
Deck .....	144959		6758BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>PPR2042STA; PPR2042STB – Continued</b>			
Ground Drive .....	130801		6758BR
<b>PPR14542A; PPR14542B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>PPRGT20H50A</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>PR20H46STA</b>			
Primary .....	148763		6702BR
<b>PR1642STA; PR1742STA; PR1742STB; PR1742STC; PR1742STD; PR1742STE; PR1742STF; PR1842STA; PR1842STB; PR1842STC</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>PR1842STD; PR2042; PR2042STA; PR17542STA; PR17542STB; PR17542STC; PR18542STA; PR18542STB; PR18542STC</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>PRGT20H50A; PRGT20H50B</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>PRGT22H48A</b>			
Ground Drive .....	161597		6551BR
<b>PRGT22H50A</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>PRGT22H50B</b>			
Ground Drive .....	161597		6551BR
<b>PRGT22H50C</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>PRGT22H50D; PRGT25H48A</b>			
Ground Drive .....	161597		6551BR
<b>PRGT2046A; PRGT2046B</b>			
Ground Drive .....	137153		6798BR
Primary .....	148763		6702BR
<b>PRK17G42STA; PRK17G42STB</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>Q12538A; Q12538B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>Q12538C</b>			
Deck Drive .....	144200		6463BR
<b>Q14542A</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>QP20H46A; QP20H46B</b>			
Primary .....	148763		6702BR
<b>QPGT22H46A; QPGT22H46B</b>			
Ground Drive .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>QPGT25H50A</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>R12R38A; R125R38A</b>			
Deck Drive .....	144200		6463BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>R12R38A; R125R38A – Continued</b>			
Ground Drive .....	126520X		6459BR
<b>R1238A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>R1238B</b>			
Deck Drive .....	144200		6463BR
<b>R14542A</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>R14542B; R14542C</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>R14542D</b>			
Deck Drive .....	144200		6463BR
<b>RE10L36B; RE10M36A</b>			
Deck .....	131264		6458BR
<b>RE11B36A; RE11B36B; RE12C36B; RE12C36D; RE12C36E</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>RE12HB36A</b>			
Deck .....	131264		6458BR
<b>RE12R38A</b>			
Deck .....	131290		6459BR
<b>RE12T38A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>RE20H46A</b>			
Drive .....	161741		6572BR
Primary .....	148763		6702BR
<b>RE91R12B; RE91R12C; RE91R12D</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>RE145H42F</b>			
Deck Drive .....	144200		6463BR
<b>RE1136A</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>RE1238C</b>			
Deck .....	131290		6459BR
<b>RE1242A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>RE1242B; RE1338A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>RE1442A; RE1842A; RE1842B</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>RE12538B; RE12538D</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>RE12542A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>RE14542D</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>RE14542F</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>RED145H36A</b>			
Deck .....	165555		6579BR
Drive .....	165632		6928BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>RELT1236A</b>			
Deck .....	174978		6811BR
Ground Drive .....	130801		6758BR
<b>RELT1236D</b>			
Deck .....	180213		6798BR
Ground Drive .....	130801		6758BR
<b>RELTS1136A; RELTS3611A</b>			
Deck .....	174978		6811BR
Ground Drive .....	130801		6758BR
<b>RELTS3611B</b>			
Deck .....	180213		6798BR
Ground Drive .....	130801		6758BR
<b>REQ11CRDB</b>			
Deck .....	180217		6579BR
<b>RER145H36A; RER145H36B; RER145H36C; RER145H36D</b>			
Deck .....	165555		6579BR
Drive .....	165632		6928BR
<b>RER1236A; RER12536A; RER12536C; RER12536E</b>			
Deck .....	165555		6579BR
<b>RGT1844D</b>			
Deck .....	106085X		6672BR
Drive .....	123554X		6894
<b>RK20H46A</b>			
Primary .....	148763		6702BR
<b>RK185H46A</b>			
Ground Drive .....	140294		6434BR
Primary .....	158818		6444BR
Secondary .....	144959		6758BR
<b>RK1742STA</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>RKGT20H46A</b>			
Drive .....	161741		6572BR
Primary .....	148763		6702BR
<b>RKGT22H46A</b>			
Ground Drive .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>RKGT25H50A</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>RL10L36A; RL10L36B; RL10L36C</b>			
Deck .....	131264		6458BR
<b>RL12N38A; RL12N38B</b>			
Deck .....	131290		6459BR
<b>RL12N38C</b>			
Deck .....	126520X		6459BR
Ground Drive .....	138255		6758BR
<b>RL12R38A</b>			
Deck .....	131290		6459BR
<b>RL12T38B</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>RL125R38A</b>			
Deck .....	131290		6459BR
<b>RL1036A</b>			
Deck .....	131264		6458BR
<b>RL1036AR; RL1036B</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>RL1136A</b>			
Deck .....	131264		6458BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>RL1138AR; RL1238C</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>RL1238D</b>			
Deck .....	131290		6459BR
<b>RL1242A; RL1442A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>RL1444AR; RL1444B</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>RL1842A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>RL1844B</b>			
Deck .....	106085X		6672BR
Drive .....	125908X		6893
<b>RL12536TA; RL12536TB; RLT10L36A</b>			
Deck .....	131264		6458BR
<b>RLT12R38A; RLT125R38A; RLT125R38B</b>			
Deck .....	131290		6459BR
<b>RLTE1238AR</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>RPL2H4E3A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>RPL2H4E6A</b>			
Deck Drive .....	144200		6463BR
<b>RPL2Q4E9A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>RR1138B; RR1238B</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>RRT12L36A</b>			
Deck .....	131264		6458BR
<b>RY1842A</b>			
Deck .....	130969		6457BR
Drive .....	131006		6898
<b>RY12542A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>RZ12542A</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>RZGT18H46A</b>			
Drive .....	161741		6572BR
<b>RZLT125H36A</b>			
Deck .....	174978		6811BR
Drive .....	140294		6434BR
<b>RZLT1236A; RZLT1236B</b>			
Deck .....	174978		6811BR
Ground Drive .....	130801		6758BR
<b>SE1342A; SE1342B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>SGT18H46A</b>			
Deck .....	131264		6458BR
<b>SGT18H46B; SGT18H46C</b>			
Drive .....	161741		6572BR
<b>SN1138A</b>			
Deck .....	180214		6627BR
Ground Drive .....	130801		6758BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>SN14542D</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>SO1538A</b>			
Deck .....	144200		6463BR
Ground Drive .....	138255		6758BR
<b>SO1542A; SO1742STA</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>SPGT25H48A</b>			
Ground Drive .....	161597		6551BR
<b>T10L36A</b>			
Deck .....	131264		6458BR
<b>T145H42A; T145H42B; T145H42C</b>			
Deck Drive .....	144200		6463BR
<b>T1136B</b>			
Deck .....	131264		6458BR
<b>T1138A</b>			
Deck .....	126520X		6459BR
Ground Drive .....	138255		6758BR
<b>T1238A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>T1238B</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>T1238C; T1238D</b>			
Deck .....	131290		6459BR
<b>T1238E; T1238F</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>T1254B</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>T1444B</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>T1444C; T1444D</b>			
Deck .....	106085X		6672BR
Drive .....	125908X		6893
<b>T1444E</b>			
Ground Drive .....	138255		6758BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>T12542A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>T12542B</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>T12542C; T12542D; T12542E; T12542F</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>TF1036AR; TF1238AR; TF1444AR</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>TM12B36A</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>TMH1450</b>			
Deck .....	165555		6579BR
<b>TMH1450H</b>			
Deck .....	165555		6579BR
Drive .....	165632		6928BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>TS14H42A</b>			
Deck .....	130969		6457BR
<b>TS15H42A</b>			
Deck Drive .....	144200		6463BR
<b>TS20CH50A</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>TS20H50A; TS20H50B</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>TS20H50C</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>TS20V51A</b>			
Ground Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>TS20VH50A</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>TS22H50A</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>TS22H50B</b>			
Ground Drive .....	140218		6811BR
<b>TS1238A</b>			
Deck .....	131290		6459BR
<b>TS1844A</b>			
Deck .....	106085X		6672BR
Drive .....	123796X		6432BR
<b>TS1844B</b>			
Ground Drive .....	138255		6758BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>TS1846A</b>			
Primary .....	148763		6702BR
<b>TS2050B; TS2050C</b>			
Ground Drive .....	137153		6798BR
<b>TS2051C</b>			
Ground Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>TS2051D</b>			
Ground Drive .....	137153		6798BR
<b>UM15H42D</b>			
Deck Drive .....	144200		6463BR
<b>VL155H36BAA</b>			
Deck .....	165555		6579BR
Drive .....	165632		6928BR
<b>VL1336BAA</b>			
Deck .....	165555		6579BR
<b>WA1338A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WA1742STA; WA15542A</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>WAGT20H48STA</b>			
Drive .....	161741		6572BR
<b>WE10L36A</b>			
Deck .....	131264		6458BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>WE12N38A</b>			
Deck .....	126520X		6459BR
Ground Drive .....	138255		6758BR
<b>WE12N38C; WE12N38D; WE12N38E</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE12R38A</b>			
Deck .....	131290		6459BR
<b>WE13T38A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE13T38B</b>			
Deck Drive .....	144200		6463BR
<b>WE13T38C; WE13T38D; WE15T42A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE17TH42A; WE18H42A</b>			
Deck Drive .....	144200		6463BR
<b>WE18N44A</b>			
Deck .....	131290		6459BR
<b>WE125N38A</b>			
Deck .....	126520X		6459BR
Ground Drive .....	138255		6758BR
<b>WE125R38A</b>			
Deck .....	131290		6459BR
<b>WE145H42A; WE145H42B</b>			
Deck Drive .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>WE145H42C; WE145H42D; WE145H42E; WE165H42A; WE165H42B</b>			
Deck Drive .....	144200		6463BR
<b>WE165T42A</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>WE185H42A; WE185H42D; WE185H42E; WE185H42F</b>			
Deck Drive .....	144200		6463BR
<b>WE185H46A</b>			
Ground Drive .....	161588		6798BR
Primary .....	158818		6444BR
Secondary .....	144959		6758BR
<b>WE185H46B</b>			
Ground Drive .....	140294		6434BR
Primary .....	158818		6444BR
Secondary .....	144959		6758BR
<b>WE1136A</b>			
Deck .....	131264		6458BR
Ground Drive .....	124525X		6889
<b>WE1236A</b>			
Deck .....	131264		6458BR
Traction .....	124525X		6889
<b>WE1236B</b>			
Deck .....	131264		6458BR
<b>WE1338A</b>			
Deck .....	144200		6463BR
Ground Drive .....	138255		6758BR
<b>WE1442A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>WE1538A; WE1538B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE1538C</b>			
Deck .....	144200		6463BR
Ground Drive .....	138255		6758BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>WE1642A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE1642B</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>WE1644A</b>			
Ground Drive .....	123796X		6432BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>WE1842A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>WE2050A</b>			
Ground Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>WE12536A</b>			
Deck .....	124293X		6880
Ground Drive .....	126520X		6459BR
<b>WE12538B; WE12538C; WE12538D; WE12538E; WE12538F; WE12538G; WE12538H; WE12538J; WE12538K; WE12538L</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE12538M</b>			
Deck .....	144200		6463BR
Ground Drive .....	138255		6758BR
<b>WE12542A; WE12542B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE12542C</b>			
Deck Drive .....	144200		6463BR
<b>WE12542D; WE12542E</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE12542F</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>WE14542A; WE14542C</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE14542D</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>WE14542E; WE14542F; WE14542G</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE14542GH</b>			
Deck Drive .....	144200		6463BR
<b>WE14542J</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE14542K; WE14542L</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>WE16542A</b>			
Deck Drive .....	144200		6463BR
<b>WE16542B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WE16542C; WE16542D; WE16542E</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>WE18542A</b>			
Deck .....	144200		6463BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>WE18542A – Continued</b>			
Ground Drive .....	130801		6758BR
<b>WE18542B</b>			
Deck .....	144959	6758BR	
Ground Drive .....	130801	6758BR	
<b>WE18542C</b>			
Deck Drive .....	144200	6463BR	
<b>WE18542D; WE18542E</b>			
Deck .....	144200	6463BR	
Ground Drive .....	130801	6758BR	
<b>WE18542F</b>			
Deck .....	144959	6758BR	
Ground Drive .....	130801	6758BR	
<b>WE18546A</b>			
Ground Drive .....	138255	6758BR	
Primary .....	158818	6444BR	
Secondary .....	144959	6758BR	
<b>WEA13H38A</b>			
Deck Drive .....	144200	6463BR	
<b>WEA1136A</b>			
Deck .....	131264	6458BR	
Ground Drive .....	126520X	6459BR	
<b>WEG14PL42A</b>			
Deck .....	140067	6551BR	
Ground Drive .....	130801	6758BR	
<b>WEG125R38A</b>			
Deck .....	126520X	6459BR	
Drive .....	124525X	6889	
<b>WEG1238A</b>			
Deck .....	126520X	6459BR	
Ground Drive .....	138255	6758BR	
<b>WEG1842A</b>			
Deck .....	140067	6551BR	
Ground Drive .....	138255	6758BR	
<b>WELT1236A</b>			
Deck .....	174978	6811BR	
Ground Drive .....	138255	6758BR	
<b>WEM125R38A</b>			
Deck .....	126520X	6459BR	
Drive .....	124525X	6889	
<b>WER14542A</b>			
Deck .....	144200	6463BR	
Ground Drive .....	130801	6758BR	
<b>WET12R38A</b>			
Deck .....	131290	6459BR	
<b>WET13T38A</b>			
Deck .....	144200	6463BR	
Ground Drive .....	130801	6758BR	
<b>WET1338A</b>			
Deck .....	144200	6463BR	
Ground Drive .....	138255	6758BR	
<b>WET1642A; WET1642B</b>			
Deck .....	144200	6463BR	
Ground Drive .....	130801	6758BR	
<b>WET1742A</b>			
Deck .....	144959	6758BR	
Ground Drive .....	130801	6758BR	
<b>WET1742B</b>			
Deck .....	144200	6463BR	
Ground Drive .....	130801	6758BR	
<b>WET1742STA; WET2242STA; WET2242STB</b>			
Deck .....	144959	6758BR	
Ground Drive .....	130801	6758BR	
<b>WET12538A; WET14542A</b>			
Deck .....	144200	6463BR	
Ground Drive .....	130801	6758BR	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>WEX12B36A</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>WEX12H36B; WEX12H36C; WEX12H36D</b>			
Deck .....	131264		6458BR
<b>WEX12TCRDA; WEX12TCRDB; WEX13TCRDA</b>			
Deck .....	165555		6579BR
<b>WEX16THCRDA</b>			
Deck .....	165555		6579BR
Drive .....	165632		6928BR
<b>WEX125CRDA</b>			
Deck .....	165555		6579BR
<b>WEX155HCRDA; WEX155HCRDB</b>			
Deck .....	165555		6579BR
Drive .....	165632		6928BR
<b>WEX1236B; WEX1236D</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>WEX1242B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WEX1242C</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>WEX1292A</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>WEY1842A</b>			
Deck .....	130969		6457BR
Drive .....	131006		6898
<b>WEY12542A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>WG15H42A</b>			
Deck Drive .....	144200		6463BR
<b>WG1036A; WG1136B; WG1136C; WG1236B; WG1236C</b>			
Deck .....	131264		6458BR
<b>WG11536B</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>WP12R38A; WP12R38B</b>			
Deck .....	131290		6459BR
<b>WP12R38C</b>			
Deck .....	126520X		6459BR
Ground Drive .....	124525X		6889
<b>WP14H38A</b>			
Deck .....	131290		6459BR
<b>WP18H44A</b>			
Deck .....	106085X		6672BR
Drive .....	123461X		6881
<b>WP18IC44A</b>			
Ground Drive .....	123796X		6432BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>WP145H42A</b>			
Deck Drive .....	144200		6463BR
<b>WP145H42B; WP145H42C</b>			
Deck Drive .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>WP145H42E; WP145H42F; WP145H42G</b>			
Deck Drive .....	144200		6463BR
<b>WP1036A</b>			
Deck .....	131264		6458BR

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>WP1238A</b>			
Deck .....	126520X		6459BR
Ground Drive .....	138255		6758BR
<b>WP1238B; WP1238C; WP1238D; WP1238E; WP1238F</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WP1254C; WP1442A</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>WP1842A; WP1842B</b>			
Deck .....	130969		6457BR
Drive .....	131006		6898
<b>WP12542A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>WP12542C</b>			
Deck .....	140067		6551BR
Ground Drive .....	138255		6758BR
<b>WP14542A; WP14542B</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WP14542C</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>WP14542E</b>			
Deck Drive .....	144200		6463BR
<b>WP14542F</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WS12538A</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>WX1238A; WX1842A; WX12542A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>WZ12B36B; WZ125H36A</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>WZ125H36B</b>			
Deck .....	131264		6458BR
<b>WZ145H42B; WZ145H42C</b>			
Deck Drive .....	144200		6463BR
<b>WZ185H46B</b>			
Ground Drive .....	140294		6434BR
Primary .....	158818		6444BR
Secondary .....	144959		6758BR
<b>WZ1236B</b>			
Deck .....	131264		6458BR
Ground Drive .....	126520X		6459BR
<b>WZ15536RDHA</b>			
Deck .....	165555		6579BR
Drive .....	165632		6928BR
<b>X12D38A</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>X12D38B</b>			
Deck .....	131290		6459BR
<b>X14V38A</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>X14V38B</b>			
Deck .....	131290		6459BR
<b>X18V44B; X18V44C</b>			
Deck .....	106085X		6672BR
Ground Drive .....	123796X		6432BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>X125R38A</b>			
Deck .....	131290		6459BR
<b>X1036A</b>			
Deck .....	124293X		6880
Ground Drive .....	124525X		6889
<b>X1236A</b>			
Deck .....	124293X		6880
Traction; W/88 3/4" Belt O.C. ....	126520X		6459BR
Traction; W/89" Belt O.C. ....	124525X		6889
<b>X1442A; X12542A</b>			
Deck .....	130969		6457BR
Drive .....	131006		6898
<b>XB12R38A; XB125R38MA</b>			
Deck .....	131290		6459BR
<b>XC1120B</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>Y10L36A; Y10L36B</b>			
Deck .....	131264		6458BR
<b>Y12R38A</b>			
Deck .....	131290		6459BR
<b>Y12R38B</b>			
Deck .....	131290		6459BR
Ground Drive .....	124525X		6889
<b>Y12R38C; Y12R38D</b>			
Deck .....	126520X		6459BR
Traction .....	124525X		6889
<b>Y14B42A</b>			
Deck .....	140067		6551BR
Ground Drive .....	130801		6758BR
<b>Y14H42A</b>			
Deck .....	130969		6457BR
<b>Y14V42A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>Y15D42A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>Y18H44A; Y18H44B; Y18H44C</b>			
Deck .....	106085X		6672BR
Drive .....	123461X		6881
<b>Y18H44D; Y18H44E</b>			
Ground Drive .....	140294		6434BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>Y19H42A</b>			
Deck Drive .....	144200		6463BR
<b>Y19H44A</b>			
Ground Drive .....	140218		6811BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>Y20C50A</b>			
Ground Drive .....	137153		6798BR
<b>Y20H50A</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>Y20H50B</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>Y20V50A</b>			
Ground Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>Y20V50B</b>			
Ground Drive .....	137153		6798BR
<b>Y20VH50A</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>Y125H38A</b>			
Deck .....	131290		6459BR
<b>Y125H42A</b>			
Deck Drive .....	144200		6463BR
<b>Y145H92RBA; Y145H92RBB; Y155H92RBA</b>			
Deck .....	165555		6579BR
Drive .....	165632		6928BR
<b>Y1238E</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>Y1242C</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>Y1242D</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>Y1292RBA; Y1292RBB</b>			
Deck .....	165555		6579BR
<b>Y1438B</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>Y1442A; Y1442B; Y1642A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>Y1642B</b>			
Deck .....	130969		6457BR
Drive .....	131006		6898
<b>Y1844A; Y1844B; Y1844C</b>			
Deck .....	106085X		6672BR
Drive .....	123796X		6432BR
<b>Y1844D; Y1844E; Y1844F</b>			
Ground Drive .....	123796X		6432BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>Y1846A</b>			
Ground Drive .....	130801		6758BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>Y1950A</b>			
Ground Drive .....	137153		6798BR
<b>Y2050D; Y2050E</b>			
Ground Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>Y12538B</b>			
Deck .....	131290		6459BR
Ground Drive .....	130801		6758BR
<b>Y12542A</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>Y12542D; Y12542E; Y12542G</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>Y12592RBA</b>			
Deck .....	165555		6579BR
<b>Y14542A; Y14542B; Y18542A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>YC125H42A</b>			
Deck .....	130969		6457BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>YC125H42C</b>			
Deck Drive .....	144200		6463BR
<b>YC1238A; YC12538A</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>YC12542A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>YE10L36B</b>			
Deck .....	131264		6458BR
<b>YE12R38A</b>			
Deck .....	131290		6459BR
<b>YE16H44C</b>			
Deck .....	106085X		6672BR
Drive .....	123461X		6881
<b>YE1236D</b>			
Deck .....	131264		6458BR
<b>YE1442A; YE12542B</b>			
Deck .....	130969		6457BR
Ground Drive .....	138255		6758BR
<b>YF1238A</b>			
Deck .....	131290		6459BR
<b>YGT18H46A</b>			
Ground Drive .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>YGT18H46B; YGT18H46C</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>YGT20H46A</b>			
Drive .....	161741		6572BR
Primary .....	148763		6702BR
<b>YGT22H50A; YGT22H50B; YGT22H50C; YGT22H50D</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>YGT1846A</b>			
Ground Drive .....	137153		6798BR
Primary .....	148763		6702BR
<b>YGT1846B</b>			
Ground Drive .....	137153		6798BR
<b>YGT2046D; YGTB18546A</b>			
Primary .....	148763		6702BR
<b>YP15H42A</b>			
Deck .....	144959		6758BR
Ground Drive .....	156971		6558BR
<b>YP15H42B</b>			
Deck Drive .....	144200		6463BR
Ground Drive .....	156971		6558BR
<b>YP15H42D; YP17H42A</b>			
Deck Drive .....	144200		6463BR
<b>YP1342A</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>YP1342B; YP1342C</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>YP1342D</b>			
Deck Drive .....	144200		6463BR
<b>YP1342E</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
<b>YP1542A</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>YP1542B; YP1542C</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>YP1946A</b>			
Ground Drive .....	130801		6758BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>YP1946C</b>			
Ground Drive .....	130801		6758BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>YPB17H42A; YPB17H42B</b>			
Deck Drive .....	144200		6463BR
<b>YPB1742A</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>YPGTK180CR</b>			
Deck .....	106085X		6672BR
Ground Drive .....	123796X		6432BR
<b>YPLR120BR</b>			
Deck .....	106085X		6672BR
Drive .....	124293X		6880
<b>YPQ20H46A</b>			
Primary .....	148763		6702BR
<b>YPQ185H46A</b>			
Ground Drive .....	140294		6434BR
Primary .....	158818		6444BR
Secondary .....	144959		6758BR
<b>YPQGT20H46A</b>			
Drive .....	161741		6572BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>YPQGT22H46A</b>			
Ground Drive .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>YPQGT25H50A</b>			
Ground Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>YT140AR; YT140BR; YT140BT; YT140CR</b>			
Deck .....	106085X		6672BR
Drive .....	125908X		6893
<b>YT140DR</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>YTH120AR; YTH160AR; YTH160AT; YTH160BR; YTH160BT; YTH160CR; YTH160CT; YTH160DR</b>			
Deck .....	106085X		6672BR
Drive .....	120418X		6880
<b>ARIENS</b>			
<b>3ML6; 3ML6D; 3ML6DE; 3ML7D; 3ML7DE</b>			
Drive .....	34X69		6941
<b>1440; 1440G</b>			
Blade .....	072115		6867
<b>3966; 3967; 3968</b>			
Blade; W/44" Belt O.C. ....	072050		6944
Blade; W/47" Belt O.C. ....	072049		6947
Drive .....	072026		6941
<b>13948</b>			
P.T.O. ....	72050	3440	6944
Primary .....	72055	1390	6739

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>13989</b>			
Blade .....	72055	1390	6739
P.T.O. ....	72050	3440	6944
<b>13990</b>			
Blade; Ser. No. 004001 & After .....	72040	1390	6739
P.T.O. ....	72050	3440	6944
Trans. ....	72057	3660	6966
<b>903001; 903002; 903003</b>			
Blade; W/44" Belt O.C. ....	72050		6944
Blade; W/47" Belt O.C. ....	72049		6947
Drive .....	72026		6941
<b>912002; 912003; 912004; 912005; 912006; 912007; 912008; 912009</b>			
Blade .....	072029		6949
Drive .....	072048	7280	
<b>912010; 912011; 912012</b>			
Blade .....	72029		6949
<b>913002; 913003</b>			
Cross Drive .....	72038		6853
P.T.O. ....	72059		6943
Transaxle .....	72040		6739
<b>914011; 914012</b>			
Traction; W/Comm. 18, 20 H.P. Eng. ....	072138		6733
<b>915013</b>			
Eng. To J.S. ....	07235700		6947
Trans. ....	07213600		6809BR
<b>915014</b>			
Cross Deck .....	07234400		68107
Eng. To Deck .....	07234500		6685BR
Eng. To J.S. ....	07235700		6947
Trans. ....	07212300		6852
<b>915017; 915018</b>			
Eng. To J.S. ....	07235700		6947
Trans. ....	07212300		6852
<b>915020; 915021</b>			
Cross Deck .....	07235500		6914BR
Eng. To Deck .....	07234300		6809BR
Eng. To J.S. ....	07235700		6947
Trans. ....	07213600		6809BR
<b>915022</b>			
Eng. To J.S. ....	07235700		6947
Trans. ....	07213600		6809BR
<b>915023</b>			
Cross Deck .....	07234400		68107
Eng. To Deck .....	07234500		6685BR
Eng. To J.S. ....	07235700		6947
Trans. ....	07213600		6809BR
<b>915306</b>			
Cross Deck .....	07234400		68107
Eng. To Deck .....	07234500		6685BR
Eng. To J.S. ....	07235700		6947
Trans. ....	07212300		6852
<b>915307</b>			
Eng. To J.S. ....	07235700		6947
Trans. ....	07212300		6852
<b>915308</b>			
Eng. To J.S. ....	07235700		6947
Trans. ....	07213600		6809BR
<b>925002; 925003; 925004; 925005</b>			
Blade .....	72042		6733
Drive .....	72052		6969
<b>925006; 925007; 925008</b>			
Blade .....	072029		6949
Deck .....	072052		6969
Trans. ....	072038		6853
<b>925009; 925011; 925012; 925013; 925014; 925015; 925017; 925018; 925020</b>			
Deck .....	072052		6969



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>925009; 925011; 925012; 925013; 925014; 925015; 925017; 925018; 925020 - Continued</b>			
Drive .....	072065		6836
<b>927001</b>			
Blade .....	072113		6865
Drive .....	072112		6735
<b>927002; 927003</b>			
Blade .....	072115		6867
Drive .....	072112		6735
<b>927004</b>			
Blade .....	072113		6865
Drive .....	072112		6735
<b>927005; 927006; 927007; 927008; 927009</b>			
Blade .....	072124		6865
Drive .....	072112		6735
<b>927010; 927011</b>			
Blade .....	072113		6865
Drive .....	072112		6735
<b>927012; 927013</b>			
Blade .....	072124		6865
Drive .....	072112		6735
<b>927014</b>			
Blade .....	072113		6865
Drive .....	072112		6735
<b>927015; 927016</b>			
Blade .....	072124		6865
Drive .....	072112		6735
<b>927017</b>			
Blade .....	072113		6865
Drive .....	072112		6735
<b>927018</b>			
Blade .....	072115		6867
Drive .....	072112		6735
<b>927020; 927021</b>			
Blade .....	072113		6865
Drive .....	072112		6735
<b>927023</b>			
Blade; 1983-1982 .....	072124		6865
Blade; 1986-1984 .....	072155		6865
Drive .....	072112		6735
<b>927024; 927025</b>			
Blade .....	072113		6865
Drive .....	072112		6735
<b>927026</b>			
Eng. To Deck .....	72113		6865
<b>927027</b>			
Blade .....	072113		6865
Drive .....	072112		6735
<b>927028</b>			
Blade; 1983-1982 .....	072124		6865
Blade; 1986-1984 .....	072155		6865
Drive .....	072112		6735
<b>927029</b>			
Blade .....	072113		6865
Drive .....	072112		6735
<b>927030</b>			
Blade; 1983-1982 .....	072124		6865
Blade; 1986-1984 .....	072155		6865
Drive .....	072112		6735
<b>927032</b>			
Eng. To Deck .....	72113		6865
<b>927033</b>			
Deck .....	72162		6864
Drive .....	72112		6735
<b>927034</b>			
Deck .....	72163		6864

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>927034 - Continued</b>			
Drive .....	72112		6735
<b>929000</b>			
Belt; W/58" Belt O.C. ....	072101		6858
Belt; W/75" Belt O.C. ....	072102	2750	
Belt; W/90" Belt O.C. ....	072103		6889
<b>929001; 929002</b>			
Drive .....	072100		6375
P.T.O. ....	072101		6858
Transaxle .....	072103		6889
<b>931011; 931012; 931013; 931014</b>			
Drive .....	072090		6933
Hyd. Lift .....	072088		6722
P.T.O. ....	072111		6834
<b>931015; 931016; 931017; 931018; 931019</b>			
P.T.O. ....	072111		6834
<b>931020; 931021</b>			
Drive .....	072090		6933
Hyd. Lift .....	072088		6722
P.T.O. ....	072111		6834
<b>931022; 931023; 931025; 931026; 931029</b>			
P.T.O. ....	072111		6834
<b>933014</b>			
Blade .....	72038		6853
Drive .....	72118		6847
<b>934001</b>			
Blade; W/50" Belt O.C. ....	072096	2500	6850
Blade; W/51" Belt O.C. ....	072136	2510	6851
Main Drive .....	072135		6968
P.T.O. ....	72147	2530	6853
Trans. ....	072134		6933
<b>934002; 934003</b>			
Main Drive .....	072135		6968
P.T.O. ....	72147		6853
Trans. ....	072134		6933
<b>934004</b>			
Blade; W/50" Belt O.C. ....	072096	2500	6850
Blade; W/51" Belt O.C. ....	072136	2510	6851
Main Drive .....	072135		6968
P.T.O. ....	72147	2530	6853
Trans. ....	072134		6933
<b>934005; 934006</b>			
Deck .....	072096	2500	6850
J.S. ....	072135		6968
<b>934015</b>			
Belt .....	72139		6896
<b>935000</b>			
Blade .....	72118		6847
Deck .....	72038		6853
Variator .....	72117		6830
<b>935001 (YT1138); 935001</b>			
Blade .....	072038		6853
Deck .....	072118		6847
Main Drive .....	072116		6871
Traction .....	072117		6830
<b>935002 (YT1032)</b>			
Blade .....	072123		6852
Main Drive .....	072116		6871
Traction .....	072117		6830
<b>935002 (YT1038); 935003 (YT1038); 935003 (YT1138)</b>			
Blade .....	072038		6853
Deck .....	072118		6847
Main Drive .....	072116		6871
Traction .....	072117		6830
<b>935004 (YT832)</b>			
Blade .....	072123		6852
Main Drive .....	072116		6871
Traction .....	072117		6830

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>935004</b>			
Blade; W/38" Deck .....	072038		6853
Deck; W/32" Deck .....	072123		6852
Deck; W/38" Deck .....	072118		6847
Main Drive .....	072116		6871
Traction .....	072117		6830
<b>935005</b>			
Blade; W/32" Deck .....	072123		6852
Blade; W/38" Deck .....	072038		6853
Deck; W/38" Deck .....	072118		6847
Main Drive; W/64" Belt O.C. ....	72161		6873
Main Drive; W/71" Belt O.C. ....	072116		6871
Traction .....	072117		6830
<b>935008</b>			
Deck .....	072123		6852
Main Drive .....	072116		6871
Traction .....	072137		6831
<b>935009 (YT1132)</b>			
Deck .....	072123		6852
Main Drive .....	072116		6871
Traction .....	072117		6830
<b>935009; 935011</b>			
Blade; W/38" Deck .....	072038		6853
Deck; W/32" Deck .....	072123		6852
Deck; W/38" Deck .....	072118		6847
Main Drive .....	072116		6871
Traction .....	072117		6830
<b>935013; 935014</b>			
Blade; W/38" Deck .....	072038		6853
Deck; W/32" Deck .....	072123		6852
Deck; W/38" Deck .....	072118		6847
Main Drive .....	72161		6873
Traction .....	072117		6830
Transaxle .....	072116		6871
<b>935015</b>			
Blade; W/38" Deck .....	072038		6853
Deck; W/32" Deck .....	072123		6852
Deck; W/38" Deck .....	072118		6847
Hydro .....	72159		6724
Wheel Drive .....	072117		6830
<b>935019</b>			
Blade; W/38" Deck .....	072038		6853
Deck; W/32" Deck .....	072123		6852
Deck; W/38" Deck .....	072118		6847
Hydro .....	72159		6724
Main Drive .....	72161		6873
Wheel Drive .....	072117		6830
<b>935019 Hydro</b>			
Deck .....	072123		6852
Hydro .....	72159		6724
Main Drive .....	072161		6873
Wheel Drive .....	72117		6830
<b>935020</b>			
Blade; W/38" Deck .....	072038		6853
Deck; W/32" Deck .....	072123		6852
Deck; W/38" Deck .....	072118		6847
Hydro .....	72159		6724
Main Drive .....	72161		6873
Traction .....	072117		6830
<b>935020 Hydro</b>			
Blade .....	072038		6853
Deck .....	072118		6847
Hydro .....	72159		6724
Main Drive .....	072161		6873
Wheel Drive .....	72117		6830
<b>FM Mowers</b>			
Deck; W/48" Belt O.C. ....	34X8700		6948
Deck; W/49" Belt O.C. ....			6949
Drive .....	34X10500		6728
<b>Garden Tractor 54</b>			
Deck Drive .....	21546382		6757BR
Drive .....	21546076		6713BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>HT1648</b>			
J.S. ....	07213	3680	6968
J.S. To Deck .....	07209	2500	6850
<b>IKON X 42</b>			
Deck Drive .....	07200523		7089BR
Transaxle .....	07200718		7073BR
<b>IKON X 52</b>			
Deck Drive .....	07200023		6708BR
Transaxle .....	07200718		7073BR
<b>IKON XL 42</b>			
Deck Drive .....	07200523		7089BR
Transaxle .....	07200724		7074BR
<b>IKON XL 52</b>			
Deck Drive .....	07200023		6708BR
Transaxle .....	07200724		7074BR
<b>Lawn Tractor 42; Lawn Tractor 46; Lawn Tractor 48</b>			
Drive .....	21546080		6767BR
<b>Lawn Tractor 54</b>			
Deck Drive .....	21546382		6757BR
Drive .....	21546080		6767BR
<b>Max Zoom 48</b>			
Blade Drive .....	07200035		6654BR
Eng. To Deck .....	07200025		7121BR
Hydro .....	07211500		6448BR
<b>Max Zoom 52</b>			
Blade Drive .....	07200036		6790BR
Eng. To Deck .....	07200026		6788BR
Hydro .....	07211500		6448BR
<b>Max Zoom 60</b>			
Blade Drive .....	07200038		6791BR
Eng. To Deck .....	07200028		6789BR
Hydro .....	07211500		6448BR
<b>Max Zoom 2552</b>			
Deck Drive .....	07200036		6790BR
Eng. To Deck .....	07200026		6788BR
Hydro Drive .....	07211500		6448BR
<b>Max Zoom 2560</b>			
Deck Drive .....	07200038		6791BR
Eng. To Deck .....	07200028		6789BR
Hydro Drive .....	07211500		6448BR
<b>MZ Zoom 1534</b>			
Deck Drive .....	07200015		6776BR
Eng. To Deck .....	07229000		6896BR
<b>MZ Zoom 1540</b>			
Deck Drive .....	07200002		6928BR
Eng. To Deck .....	07229000		6896BR
<b>Pro Zoom 54</b>			
Blade Drive .....	00181036		6665BR
Eng. To Deck .....	00181715		6665BR
Hydro Drive .....	00181727		6943BR
<b>Pro Zoom 60</b>			
Blade Drive .....	00112616		6589BR
Eng. To Deck .....	00181715		6665BR
Hydro Drive .....	00181727		6943BR
<b>Pro Zoom 66</b>			
Blade Drive .....	00181711		6946BR
Eng. To Deck .....	00181715		6665BR
Hydro Drive .....	00181727		6943BR
<b>Pro Zoom 1952S</b>			
Deck Drive .....	07200120		6492BR
Hydro Drive .....	07200118		6559BR
<b>RM626; RM728; RM830; RM830E; RM832</b>			
Drive .....	72112		6735
P.T.O. ....	72155		6865
<b>RM1030</b>			
Eng. To Deck .....	72113		6865



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>RM1032; RM1232; RM1332</b>			
Drive .....	72112		6735
P.T.O. ....	72155		6865
<b>Yardster 400 Series</b>			
Mower .....	34X22	2380	6838
Tiller Attachment; W/29" Belt O.C. ....	31X24	2290	6829
Tiller Attachment; W/35" Belt O.C. ....	34X20	2350	6835
Traction .....	34X17	2280	6828
<b>Zoom 34</b>			
Deck Drive .....	07200116		6944BR
Hydro. ....	07200010		6498BR
<b>Zoom 42</b>			
Deck Drive .....	07200523		7089BR
Hydro. ....	07200010		6498BR
<b>Zoom 50</b>			
Deck Drive .....	07200524		6978BR
Hydro. ....	07200010		6498BR
<b>Zoom 1540</b>			
Deck Drive .....	07200001		6662BR
Eng. To Deck .....	07221000		6581BR
<b>Zoom 1634</b>			
Deck Drive .....	07200116		6944BR
Eng. To Deck .....	07237900		6792BR
<b>Zoom 1640; Zoom 1740</b>			
Deck Drive .....	07241800		6945BR
Hydro. Drive .....	07241400		6943BR
<b>Zoom 1840</b>			
Deck Drive .....	07241800		6945BR
Eng. To Deck .....	07237900		6792BR
<b>Zoom 1844</b>			
Deck Drive .....	07241700		7100BR
Eng. To Deck .....	07221000		6581BR
<b>Zoom 1844XL</b>			
Deck Drive .....	07241600		6716BR
Eng. To Deck .....	07200010		6498BR
<b>Zoom 1944</b>			
Deck Drive .....	07241700		7100BR
Eng. To Deck .....	07221000		6581BR
<b>Zoom 2040</b>			
Deck Drive .....	07241800		6945BR
Eng. To Deck .....	07237900		6792BR
<b>Zoom 2042XL</b>			
Deck Drive .....	07219600		6486BR
Eng. To Deck .....	07242200		6793BR
<b>Zoom 2048; Zoom 2148</b>			
Deck Drive .....	07241500		6727BR
Hydro. Drive .....	07241400		6943BR
<b>Zoom 2148XL</b>			
Deck Drive .....	07241600		6716BR
Eng. To Deck .....	07200010		6498BR
<b>Zoom 2252</b>			
Deck Drive .....	07241600		6716BR
Hydro. Drive .....	07241400		6943BR
<b>Zoom 2350</b>			
Deck Drive .....	07200107		7054BR
Eng. To Deck .....	07237900		6792BR
<b>Zoom 2352</b>			
Deck Drive .....	07241600		6716BR
Eng. To Deck .....	07221000		6581BR
<b>Zoom 2548XL</b>			
Deck Drive .....	07200436		6842BR
Eng. To Deck .....	07242200		6793BR
<b>Zoom XL 42</b>			
Deck Drive .....	07219600		6486BR
Hydro. ....	07242200		6793BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>Zoom XL 48</b>			
Deck Drive .....	07200436		6842BR
Hydro. ....	07242200		6793BR
<b>Zoom XL 54</b>			
Deck Drive .....	07200023		6708BR
Hydro. ....	07242200		6793BR
<b>ATLAS</b>			
<b>ER2600; ER2650</b>			
Drive .....	10722		6851
<b>ER2680</b>			
Blade .....	10731	2330	6833
Trans. ....	10732	3580	6958
<b>ER3000</b>			
Drive .....	10713		6370
<b>ER3280</b>			
Blade .....	10729		6843
Eng. To Blade .....	10730		6861
Trans. ....	10727		6835
<b>ER7130</b>			
Blade .....	10720		6974
Drive .....	10713		6370
<b>NR2651</b>			
Blade .....	10728		6853
Trans. ....	10727		6835
<b>NR2680</b>			
Blade .....	10731	2330	6833
Trans. ....	10732	3580	6958
<b>NR3280</b>			
Blade .....	10729		6843
Eng. To Blade .....	10730		6861
Trans. ....	10727		6835
<b>R25; R25A</b>			
Blade .....	10714	2188	
Drive .....	10713		6370
<b>R2600; R2650</b>			
Drive .....	10722		6851
<b>R2651</b>			
Blade .....	10728		6853
Trans. ....	10727		6835
<b>R2652</b>			
Drive .....	10722		6851
<b>R2680</b>			
Blade .....	10731	2330	6833
Trans. ....	10732	3580	6958
<b>R3000</b>			
Blade .....	10726		6974
Drive .....	10713		6370
<b>R3280</b>			
Blade .....	10729		6843
Eng. To Blade .....	10730		6861
Trans. ....	10727		6835
<b>R4124; R5124</b>			
Drive .....	10713		6370
<b>R5240; R5245</b>			
Drive .....	10722		6851
<b>R7130; R7130A</b>			
Blade .....	10720		6974
Drive .....	10713		6370
<b>TC30ER; TC30R</b>			
Blade .....	10726		6974
Trans. ....	10713		6370
<b>AUTOMOTIVE ASSOCIATES</b>			
<b>130-340; 130-362</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847

Lawn & Garden Equipment





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AUTOMOTIVE ASSOCIATES - Continued</b>			
<b>130-391; 130-393</b>			
Blade .....	7540107		6830
Trans .....	7540111	2450	6845
<b>130-410</b>			
Blade .....	7540138	3500	6950
Trans .....	7540101		6517BR
<b>130-420; 130-430</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>130-460; 130-470</b>			
Blade .....	7540118		6963
Trans .....	7540937	3590	6959
<b>130-480; 130-490</b>			
Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
<b>131-362</b>			
Blade .....	7540107		6830
Trans .....	7540936		6847
<b>131-390; 131-391</b>			
Blade .....	7540107		6830
Trans .....	7540111	2450	6845
<b>131-410; 131-412</b>			
Blade .....	7540138	3500	6950
Trans .....	7540101		6517BR
<b>131-425; 131-435</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>131-460; 131-470</b>			
Blade .....	7540118		6963
Trans .....	7540937	3590	6959
<b>131-485</b>			
Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
<b>132-360</b>			
Blade .....	7540107		6830
Trans .....	7540936		6847
<b>132-390</b>			
Blade; W/25" Deck .....	7540138	3500	6950
Drive .....	7540164	2630	6863
<b>132-410; 132-412</b>			
Blade .....	7540138	3500	6950
Trans .....	7540101		6517BR
<b>132-416; 132-418</b>			
Blade .....	7540147	3520	6952
Trans .....	7540135		6925
Variable Speed .....	7540136		6931
<b>132-425; 132-435</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>132-465</b>			
Drive .....	7540127		6966
<b>133-360</b>			
Blade .....	7540107		6830
Trans .....	7540936		6847
<b>133-390</b>			
Blade; W/25" Deck .....	7540138	3500	6950
Drive .....	7540164	2630	6863
<b>133-410</b>			
Blade .....	7540138	3500	6950
Trans .....	7540101		6517BR
<b>133-420</b>			
Blade .....	7540147	3520	6952

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AUTOMOTIVE ASSOCIATES - Continued</b>			
<b>133-420 - Continued</b>			
Trans .....	7540135		6925
Variable Speed .....	7540136		6931
<b>133-430</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>133-435</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
Trans .....	7540126		6820
<b>133-440</b>			
Blade .....	7540178	3820	6982
Drive .....	7540185		6849
<b>133-470; 133-475; 133-480</b>			
Drive .....	7540127		6966
<b>134-360</b>			
Blade .....	7540107		6830
Trans .....	7540936		6847
<b>134-380; 134-390</b>			
Blade; W/25" Deck .....	7540138	3500	6950
Drive .....	7540164	2630	6863
<b>134-406; 134-410</b>			
Drive .....	7540136		6931
<b>134-420</b>			
Blade .....	7540147	3520	6952
Trans .....	7540135		6925
Variable Speed .....	7540136		6931
<b>134-430; 134-435; 134-465</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>134-480; 134-485</b>			
Drive .....	7540127		6966
<b>134-495</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>135-340; 135-360</b>			
Blade .....	7540935	2310	6831
Trans .....	7540936		6847
<b>135-380</b>			
Blade .....	7540198		6451BR
Trans .....	7540138	3500	6950
<b>135-390</b>			
Blade .....	7540167		6964
Trans .....	7540198		6451BR
<b>135-410</b>			
Blade .....	7540138	3500	6950
Trans .....	7540101		6517BR
<b>135-430</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>135-480; 135-485</b>			
Blade .....	7540151		6967
Trans .....	7540191		6865
<b>135-495</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>136-330</b>			
Drive .....	7540100	2180	6818
<b>136-340; 136-360</b>			
Blade .....	7540935	2310	6831
Trans .....	7540936		6847





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AUTOMOTIVE ASSOCIATES - Continued</b>			
<b>136-380</b>			
Blade .....	7540198		6451BR
Trans. ....	7540138	3500	6950
<b>136-390</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>136-410</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>136-420</b>			
Blade .....	7540147	3520	6952
Trans. ....	7540135		6925
Variable Speed .....	7540136		6931
<b>136-430</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>136-480; 136-485</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>136-495</b>			
Blade .....	7540145	3370	6488BR
Drive; W/37" Belt O.C. ....	7540173		6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>136-525</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>137-380</b>			
Blade .....	7540198	3500	6451BR
Trans. ....	7540138		6950
<b>137-390</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>137-410</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>137-420</b>			
Blade .....	7540147	3520	6952
Trans. ....	7540135		6925
Variable Speed .....	7540136		6931
<b>137-430</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>137-485</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>137-495; 137-497</b>			
Blade .....	7540145	3370	6488BR
Drive; W/37" Belt O.C. ....	7540173		6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>137-525</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>138-340; 138-362</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936		6847
<b>138-420</b>			
Blade .....	7540127		6966
Trans. ....	7540128		6935
<b>138-460; 138-462</b>			
Blade .....	7540118		6963
Trans. ....	7540937		6959
<b>139-0391</b>			
Blade .....	7540105	2450	6830
Trans. ....	7540111		6845

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AUTOMOTIVE ASSOCIATES - Continued</b>			
<b>140-660; 140-665</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>140-960</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>141-668</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>141-960; 141-990</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>142-669</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>142-960</b>			
P.T.O. ....	7540165		6834
<b>143-660</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Trans. ....	7540182	3810	6981
<b>143-960</b>			
P.T.O. ....	7540165		6834
<b>144-660</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>144-960</b>			
P.T.O. ....	7540165		6834
<b>145-660</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Trans. ....	7540182	3810	6981
<b>145-960</b>			
Gen. ....	7540134	7330	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>146-650; 146-660</b>			
Drive .....	7540112	3800	6980
<b>146-960</b>			
Gen. ....	7540134	7330	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>148-860</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>BAD BOY MOWERS</b>			
<b>2MZ42</b>			
Deck Drive .....	041-0120-00		6589BR
Pump Drive .....	041-6400-00		6750BR
<b>2MZ48</b>			
Deck Drive .....	041-6027-00		6946BR
Pump Drive .....	041-6400-00		6750BR
<b>4200 Compact Outlaw</b>			
Deck Drive .....	041-4022-00		6906BR
Pump .....	041-6400-00		6750BR
<b>4200 CZT</b>			
Deck Drive .....	041-4022-00		6906BR
Pump Drive .....	041-6400-00		6750BR
<b>4800 Compact Outlaw</b>			
Deck Drive .....	041-1470-00		6692BR
Pump .....	041-6400-00		6750BR
<b>4800 CZT Elite</b>			
Deck Drive .....	041-1470-00		6692BR
Pump Drive .....	041-6400-00		6750BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BAD BOY MOWERS - Continued</b>			
<b>4800 Maverick</b>			
Deck Drive .....	041-1470-00		6692BR
<b>4800 MZ Magnum</b>			
Deck Drive .....	041-1470-00		6692BR
Pump Drive .....	041-6400-00		6750BR
<b>4800 Outlaw Revolt</b>			
Deck Drive .....	041-5200-00		7041BR
Pump Drive .....	041-8052-00		6735BR
<b>4800 Outlaw Stander</b>			
Deck Drive .....	041-5200-00		7041BR
Pump Drive .....	041-6400-00		6750BR
<b>4800 Pup</b>			
Deck Drive .....	041-1420-00		6759BR
Pump .....	041-5048-00		6751BR
<b>4800 ZT Elite; 5000 CZT</b>			
Deck Drive .....	041-1470-00		6692BR
Pump Drive .....	041-6400-00		6750BR
<b>5200 Lightning Z</b>			
Deck Drive; 2010 & Older .....	041-1490-00		6732BR
Deck Drive; 2011 .....	041-1650-00		6747BR
Pump .....	041-5048-00		6751BR
<b>5200 Pup</b>			
Deck Drive .....	041-1490-00		6732BR
Pump .....	041-5048-00		6751BR
<b>5400 CZT Elite</b>			
Deck Drive .....	041-1560-00		6997BR
Pump Drive .....	041-6400-00		6750BR
<b>5400 Maverick</b>			
Deck Drive .....	041-1560-00		6997BR
<b>5400 MZ Magnum</b>			
Deck Drive .....	041-1560-00		6997BR
Pump Drive .....	041-6400-00		6750BR
<b>5400 Outlaw; 5400 Outlaw Extreme</b>			
Deck Drive .....	041-1650-00		6747BR
Pump; 2014 & Older .....	041-5048-00		6751BR
Pump; 2015 & Newer .....	041-8411-00		6969BR
<b>5400 Outlaw Rebel</b>			
Deck Drive .....	041-1650-00		6747BR
<b>5400 Outlaw Revolt</b>			
Deck Drive .....	041-0120-00		6589BR
Pump Drive .....	041-8052-00		6735BR
<b>5400 Outlaw Rogue</b>			
Deck Drive .....	041-1650-00		6747BR
<b>5400 Outlaw Stander</b>			
Deck Drive .....	041-0120-00		6589BR
Pump Drive .....	041-6400-00		6750BR
<b>5400 Outlaw XP</b>			
Deck Drive .....	041-1650-00		6747BR
Pump; 2014 & Older .....	041-5048-00		6751BR
Pump; 2015 & Newer .....	041-8411-00		6969BR
<b>5400 ZT Elite</b>			
Deck Drive .....	041-1560-00		6997BR
Pump Drive .....	041-6400-00		6750BR
<b>6000 AOS</b>			
Deck Drive .....	041-0219-00		6947BR
Pump .....	041-5048-00		6751BR
<b>6000 AOSD</b>			
Deck Drive .....	041-0236-00		6972BR
Pump .....	041-8411-00		6969BR
<b>6000 COMD</b>			
Deck Drive .....	041-0236-00		6972BR
Pump Drive .....	041-8411-00		6969BR
<b>6000 Compact</b>			
Pump .....	041-5048-00		6751BR
<b>6000 CZT; 6000 CZT Elite</b>			
Deck Drive .....	041-1650-00		6747BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BAD BOY MOWERS - Continued</b>			
<b>6000 CZT; 6000 CZT Elite - Continued</b>			
Pump Drive .....	041-6400-00		6750BR
<b>6000 Lightning Z</b>			
Deck Drive; 2010 & Older .....	041-1650-00		6747BR
Deck Drive; 2011 .....	041-0178-00		6970BR
Pump .....	041-5048-00		6751BR
<b>6000 Maverick</b>			
Deck Drive .....	041-1650-00		6747BR
<b>6000 Pup</b>			
Deck Drive .....	041-1650-00		6747BR
Pump .....	041-5048-00		6751BR
<b>6000 ZT Elite</b>			
Deck Drive .....	041-1650-00		6747BR
Pump Drive .....	041-6400-00		6750BR
<b>6100 AOSD</b>			
Deck Drive .....	041-0236-00		6972BR
Pump .....	041-5048-00		6751BR
<b>6100 COMD</b>			
Pump .....	041-5048-00		6751BR
<b>6100 Compact Diesel; 6100 Full Size Diesel</b>			
Deck Drive .....	041-0236-00		6972BR
Pump .....	041-5048-00		6751BR
<b>6100 Outlaw; 6100 Outlaw Extreme</b>			
Deck Drive .....	041-0178-00		6970BR
Pump; 2014 & Older .....	041-5048-00		6751BR
Pump; 2015 & Newer .....	041-8411-00		6969BR
<b>6100 Outlaw Rebel; 6100 Outlaw Rogue</b>			
Deck Drive .....	041-0178-00		6970BR
<b>6100 Outlaw Stander</b>			
Deck Drive .....	041-4022-00		6906BR
Pump Drive .....	041-6400-00		6750BR
<b>6100 Outlaw XP</b>			
Deck Drive .....	041-0178-00		6970BR
Pump; 2014 & Older .....	041-5048-00		6751BR
Pump; 2015 & Newer .....	041-8411-00		6969BR
<b>7200 AOS</b>			
Deck Drive; 2008-2007 .....	041-0236-00		6972BR
Deck Drive; 2009 .....	041-2375-00		7043BR
Pump .....	041-5048-00		6751BR
<b>7200 AOSD; 7200 Full Size Diesel</b>			
Pump .....	041-8411-00		6969BR
<b>7200 Lightning Z</b>			
Deck Drive; 2010 & Older .....	041-1890-00		7042BR
Deck Drive; 2011 .....	041-0202-00		6971BR
Pump .....	041-5048-00		6751BR
<b>7200 Outlaw Extreme</b>			
Deck Drive .....	041-0202-00		6971BR
Pump; 2014 & Older .....	041-5048-00		6751BR
Pump; 2015 & Newer .....	041-8411-00		6969BR
<b>7200 Outlaw Rebel</b>			
Deck Drive .....	041-0202-00		6971BR
<b>7200 Outlaw Renegade</b>			
Deck Drive .....	041-2375-00		7043BR
<b>7200 Outlaw Rogue</b>			
Deck Drive .....	041-0202-00		6971BR
<b>7200 Outlaw XP</b>			
Deck Drive .....	041-0202-00		6971BR
Pump; 2014 & Older .....	041-5048-00		6751BR
Pump; 2015 & Newer .....	041-8411-00		6969BR
<b>CZT</b>			
Deck Drive; W/42" Deck; 2010 & Older ..	041-0120-00		6589BR
Deck Drive; W/50" Deck .....	041-1470-00		6692BR
Deck Drive; W/60" Deck .....	041-1650-00		6747BR
Pump .....	041-6400-00		6750BR
<b>MZ</b>			
Deck Drive; W/42" Deck .....	041-0120-00		6589BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BAD BOY MOWERS - Continued</b>			
<b>MZ – Continued</b>			
Deck Drive; W/48" Deck	041-6027-00		6946BR
Pump	041-6400-00		6750BR
<b>MZ42</b>			
Deck Drive	041-4022-00		6906BR
Pump Drive	041-6400-00		6750BR
<b>MZ48</b>			
Deck Drive	041-6027-00		6946BR
Pump Drive	041-6400-00		6750BR
<b>Outlaw</b>			
Deck Drive; W/54" Deck	041-1650-00		6747BR
Deck Drive; W/72" Deck	041-0202-00		6971BR
Pump	041-5048-00		6751BR
<b>ZT 2300</b>			
Deck Drive; W/50" Deck	041-1470-00		6692BR
Deck Drive; W/60" Deck	041-1650-00		6747BR
<b>ZT 2600; ZT 2700</b>			
Deck Drive; W/50" Deck	041-1470-00		6692BR
Deck Drive; W/60" Deck	041-1650-00		6747BR
Pump	041-6400-00		6750BR
<b>ZT 3600</b>			
Pump	041-6400-00		6750BR
<b>ZT 5000</b>			
Deck Drive; 2009 & Older	041-1420-00		6759BR
Deck Drive; 2010 & Newer	041-1470-00		6692BR
Pump	041-6400-00		6750BR
<b>ZT 6000</b>			
Deck Drive	041-1650-00		6747BR
Pump	041-6400-00		6750BR
<b>BIG WHEEL</b>			
<b>4000; 4400</b>			
Blade	104475	2480	6848
Deck Drive; W/51" Belt O.C.; 1973 & Older			6851
Deck Drive; W/55" Belt O.C.; 1987 & Older			6855
Deck Drive; W/60" Belt O.C.; 1987 & Newer	104476		6860
Forward	104150		6851
Reverse	104147	2270	6827
<b>BIGDOG MOWERS</b>			
<b>A 336</b>			
Deck Drive	771824		6923BR
Hydro. Drive	602253		6448BR
<b>A 342</b>			
Deck Drive	603739		6977BR
Hydro. Drive	602253		6448BR
<b>A 346</b>			
Deck Drive	600734		6727BR
Hydro. Drive	602253		6448BR
<b>ALPHA</b>			
Deck Drive; W/36" Deck	771824		6923BR
Deck Drive; W/42" Deck	793828		6848BR
Deck Drive; W/52" Deck	791988		6906BR
<b>ALPHA MP</b>			
Deck Drive; W/36" Deck	603806		7029BR
Deck Drive; W/42" Deck	606016		7048BR
Deck Drive; W/48" Deck	604830		6785BR
Deck Drive; W/60" Deck	604711		6597BR
<b>BLACKJACK</b>			
Deck Drive; W/48" Deck	602078		6878BR
Deck Drive; W/54" Deck	797720		6802BR
<b>C 142</b>			
Deck Drive	600726		6684BR
Hydro. Drive; 2010 & Older	769133		6448BR
Hydro. Drive; 2011 & Newer	797514		6743BR
<b>C 146</b>			
Deck Drive	771824		6923BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BIGDOG MOWERS - Continued</b>			
<b>C 146 – Continued</b>			
Hydro. Drive; 2010 & Older	769133		6448BR
Hydro. Drive; 2011 & Newer	797514		6743BR
<b>C 154</b>			
Deck Drive	777185		6567BR
Hydro. Drive; 2010 & Older	769133		6448BR
Hydro. Drive; 2011 & Newer	797514		6743BR
<b>DIABLO</b>			
Deck Drive; W/52" Deck	789388		6732BR
Deck Drive; W/60" Deck	782292		6733BR
Deck Drive; W/72" Deck	602854		6761BR
Hydro. Drive	601947		6735BR
<b>DIABLO MP</b>			
Deck Drive; W/60" Deck; Ser. No. 16114411 & Before	603803		6770BR
Deck Drive; W/60" Deck; Ser. No. 16114412 & After	600929		6747BR
Deck Drive; W/72" Deck; Ser. No. 16114411 & Before	602860		6920BR
Deck Drive; W/72" Deck; Ser. No. 16114412 & After	797936		6784BR
<b>R 748; R 748 POWER BAR</b>			
Deck Drive	777185		6567BR
Hydro. Drive	602253		6448BR
<b>R 754; R 754 DIABLO; R 754 POWER BAR</b>			
Deck Drive	789388		6732BR
Hydro. Drive	602253		6448BR
<b>R 760; R 760 DIABLO; R 760 POWER BAR</b>			
Deck Drive	601715		6859BR
Hydro. Drive	602253		6448BR
<b>STOUT</b>			
Deck Drive; W/48" Deck; 2015 & Older	777185		6567BR
Deck Drive; W/48" Deck; 2016 & Newer	791335		7057BR
Deck Drive; W/54" Deck; 2015 & Older	789388		6732BR
Deck Drive; W/54" Deck; 2016 & Newer	786483		6692BR
Deck Drive; W/60" Deck; 2015 & Older	601715		6859BR
Hydro. Drive; 2015 & Older	602253		6448BR
Hydro. Drive; 2016 & Newer	605468		6890BR
<b>STOUT MP</b>			
Deck Drive; W/48" Deck	791335		7057BR
Deck Drive; W/54" Deck; 2015 & Older	789388		6732BR
Deck Drive; W/54" Deck; 2016 & Newer	786483		6692BR
Deck Drive; W/60" Deck; 2015 & Older	601715		6859BR
Hydro. Drive; 2015 & Older	602253		6448BR
Hydro. Drive; 2016 & Newer	605468		6890BR
<b>Trooper</b>			
Deck Drive; W/48" Deck	601788		6646BR
Deck Drive; W/52" Deck	786491		6566BR
<b>X 1052</b>			
Deck Drive	789388		6732BR
Hydro. Drive	601947		6735BR
<b>X 1060</b>			
Deck Drive	782292		6733BR
Hydro. Drive	601947		6735BR
<b>X 1060 DIABLO</b>			
Deck Drive	603803		6770BR
<b>X 1072</b>			
Deck Drive	602854		6761BR
Hydro. Drive	601947		6735BR
<b>X 1072 DIABLO</b>			
Deck Drive	602860		6920BR
<b>BLACK, SIVALLS AND BRYSON</b>			
<b>454-1; 454-2; 456-1</b>			
Belt; W/26" Belt O.C.	448		6826
Belt; W/31" Belt O.C.	445	2310	6831

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BLUE GRASS</b>			
<b>115-672</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>115-990</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540169	7355	
<b>134-504</b>			
Eng. To Deck .....	7540264		6639BR
Primary Variator .....	7540241		6494BR
Secondary Variator .....	7540240		6511BR
<b>144-824</b>			
Deck .....	7540230		6755BR
J.S. ....	7540245		6859
Transaxle .....	7540244		6840
<b>BG668-4</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>BG832RE</b>			
Blade .....	19887	2550	6855
<b>BG834RE</b>			
Blade .....	7540178	3820	6982
Drive .....	7540185		6849
<b>BG1038</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>BG5444</b>			
Blade .....	8672B		6825
Trans. ....	9407B		6831
<b>BG6525; BG6725</b>			
Blade .....	8672B		6825
Trans. ....	8671B		6829
<b>BG6744</b>			
Blade .....	8672B		6825
Trans. ....	9407B		6831
<b>BG6765</b>			
Blade .....	8672B		6825
Trans. ....	8671B		6829
<b>BG6824</b>			
Blade .....	8672B		6825
Trans. ....	9407B		6831
<b>BG6826</b>			
Blade .....	8672B		6825
Trans. ....	8671B		6829
<b>BG6832E; BG6932B</b>			
Blade .....	14197	2280	6828
Trans. ....	8671B		6829
<b>BG6959</b>			
Blade .....	8672B		6825
Trans. ....	8671B		6829
<b>BG7032EL; BG7232EL</b>			
Blade .....	15482	2520	6852
Trans. ....	15342		6855
<b>BG7626RE</b>			
Blade .....	19887	2550	6855
<b>BG8832</b>			
Blade .....	15482	2520	6852
Trans. ....	15342		6855
<b>BR45</b>			
Trans. ....	9407B		6831
<b>BR4133</b>			
Blade .....	8672B		6825
Trans. ....	9407B		6831

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BLUE GRASS - Continued</b>			
<b>C726RE</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>C6854</b>			
Blade .....	8672B		6825
Trans. ....	9407B		6831
<b>Peerless Transaxle</b>			
Belt .....	7540266		6775BR
<b>W7-B392</b>			
Blade .....	7540167		6964
Drive .....	7540198		6451BR
<b>W7-BG465; W7-BG465-D</b>			
Blade .....	7540151		6957
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>W7-BG497; W7-BG498-D</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>W7-BG672TR</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>W7-BG796</b>			
Drive; W/42" Belt O.C. ....	7540207		6842
Drive; W/62" Belt O.C. ....	7540198		6451BR
<b>W7-BG860</b>			
Trans. ....	7540217		6979
<b>W7-BG918A</b>			
Eng. ....	7540210		6960
Trans. ....	7540212		6945
<b>W7-BG990TR</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540169	7355	
<b>BOBCAT</b>			
<b>742240</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2188175		6721BR
Hydro. Drive .....	2188128		6530BR
<b>742241</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2722224		6857BR
Hydro. Drive .....	2188128		6530BR
<b>742242</b>			
Blade Drive .....	4135683		6804BR
Eng. To Deck .....	2722554		6805BR
Hydro. Drive .....	2188128		6530BR
<b>912360</b>			
Hydro. Drive .....	2721642		7011BR
<b>942200</b>			
Blade Drive; W/48" Deck .....	128110		6615BR
Blade Drive; W/52" Deck .....	2188176		6574BR
Blade Drive; W/61" Deck .....	128003		6485BR
Eng. To Deck; W/48" Deck .....	2720815		6806BR
Eng. To Deck; W/52" Deck .....	2188175		6721BR
Eng. To Deck; W/61" Deck .....	2188134		6480BR
Traction .....	2188128		6530BR
<b>942201</b>			
Blade Drive; W/48" Deck .....	128110		6615BR
Eng. To Deck; W/48" Deck .....	2720815		6806BR
Traction .....	2188128		6530BR
<b>942202</b>			
Blade Drive; W/48" Deck .....	128110		6615BR
Blade Drive; W/52" Deck .....	2188176		6574BR
Blade Drive; W/61" Deck .....	128003		6485BR
Eng. To Deck; W/48" Deck .....	2720815		6806BR
Eng. To Deck; W/52" Deck .....	2188175		6721BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOBCAT - Continued</b>			
<b>942202 – Continued</b>			
Eng. To Deck; W/61" Deck .....	2188134		6480BR
Traction .....	2188128		6530BR
<b>942203; 942204</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2188175		6721BR
Traction .....	2188128		6530BR
<b>942206</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2188134		6480BR
Traction .....	2188128		6530BR
<b>942207; 942211</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2188175		6721BR
Traction .....	2188128		6530BR
<b>942211A</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2720815		6806BR
Traction .....	2188128		6530BR
<b>942212</b>			
Blade Drive; W/52" Deck .....	2188176		6574BR
Blade Drive; W/60" Deck .....	128003		6485BR
Blade Drive; W/61" Deck .....	128003		6485BR
Eng. To Deck; W/52" Deck .....	2188175		6721BR
Eng. To Deck; W/61" Deck .....	2188134		6480BR
Traction .....	2188128		6530BR
<b>942212A</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2720815		6806BR
Traction .....	2188128		6530BR
<b>942213; 942215</b>			
Blade Drive; W/52" Deck .....	2188176		6574BR
Blade Drive; W/60" Deck .....	128003		6485BR
Blade Drive; W/61" Deck .....	128003		6485BR
Eng. To Deck; W/52" Deck .....	2188175		6721BR
Eng. To Deck; W/61" Deck .....	2188134		6480BR
Traction .....	2188128		6530BR
<b>942218</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2720815		6806BR
Hydro. ....	4162583		6890BR
<b>942219</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2188134		6480BR
Hydro. ....	4162583		6890BR
<b>942220; 942220A</b>			
Blade Drive .....	128110		6615BR
Eng. To Deck .....	2720815		6806BR
Traction .....	2188128		6530BR
<b>942221; 942221A; 942222; 942222A</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2720815		6806BR
Traction .....	2188128		6530BR
<b>942223; 942223A; 942224; 942224A</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2188134		6480BR
Traction .....	2188128		6530BR
<b>942225</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2188134		6480BR
<b>942226</b>			
Blade Drive .....	128003		6485BR
<b>942227; 942227A</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2720815		6806BR
Traction .....	2188128		6530BR
<b>942228; 942228A</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2188134		6480BR
Traction .....	2188128		6530BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOBCAT - Continued</b>			
<b>942230; 942230A</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2722224		6857BR
Traction .....	2188128		6530BR
<b>942231; 942231A</b>			
Eng. To Deck .....	2722554		6805BR
Traction .....	2188128		6530BR
<b>942233A</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2188134		6480BR
Traction .....	2188128		6530BR
<b>942236</b>			
Blade Drive .....	128003		6485BR
<b>942237</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2188134		6480BR
Traction .....	4162583		6890BR
<b>942237A</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2188134		6480BR
Traction .....	2188128		6530BR
<b>942238A</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2722224		6857BR
Traction .....	2188128		6530BR
<b>942239A</b>			
Eng. To Deck .....	2722554		6805BR
Traction .....	2188128		6530BR
<b>942240</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2720815		6806BR
Hydro.; 2008 & Older .....	2188128		6530BR
Hydro.; 2009 & Newer .....	4161305		6889BR
<b>942241</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2722224		6857BR
Hydro.; 2008 & Older .....	2188128		6530BR
Hydro.; 2009 & Newer .....	4161305		6889BR
<b>942242</b>			
Blade Drive .....	4135683		6804BR
Eng. To Deck .....	2722554		6805BR
Hydro.; 2008 & Older .....	2188128		6530BR
Hydro.; 2009 & Newer .....	4161305		6889BR
<b>942245</b>			
Blade Drive .....	128003		6485BR
Hydro. Drive .....	4161304		6861BR
<b>942250; 942251</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2720815		6806BR
Traction .....	4162583		6890BR
<b>942252</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2188134		6480BR
Traction .....	4162583		6890BR
<b>942253</b>			
Blade Drive .....	128003		6485BR
Traction .....	4157920		6891BR
<b>942254</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2188134		6480BR
Traction .....	4162583		6890BR
<b>942255; 942256</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2722224		6857BR
Traction .....	4161305		6889BR
<b>942257</b>			
Blade Drive .....	128003		6485BR
Eng. To Deck .....	2188134		6480BR
Traction .....	4161305		6889BR

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOBCAT - Continued</b>			
<b>942258</b>			
Blade Drive .....	4135683		6804BR
Eng. To Deck .....	2722554		6805BR
Traction .....	4161305		6889BR
<b>942259</b>			
Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2720815		6806BR
Traction .....	4162583		6890BR
<b>942290; 942291</b>			
Deck Drive .....	4144212		6981BR
Transaxle .....	4143636		6807BR
<b>942293</b>			
Deck Drive .....	4147716		6778BR
Transaxle .....	4143636		6807BR
<b>942295</b>			
Deck Drive .....	4147095		6759BR
Transaxle .....	4143636		6807BR
<b>942296</b>			
Deck Drive .....	4143733		6746BR
Transaxle .....	4143636		6807BR
<b>942297F; 942297G; 942297H</b>			
Deck Drive .....	4144212		6981BR
Transaxle .....	4143636		6807BR
<b>942298F; 942298G; 942298H</b>			
Deck Drive .....	4147095		6759BR
Transaxle .....	4143636		6807BR
<b>942299F; 942299G</b>			
Deck Drive .....	4143733		6746BR
Transaxle .....	4143636		6807BR
<b>942299H</b>			
Deck Drive .....	4168470		6746BR
Transaxle .....	4143636		6807BR
<b>942302F; 942302G</b>			
Deck Drive .....	4147716		6778BR
Transaxle .....	4143636		6807BR
<b>942302H</b>			
Deck Drive; Ser. No. 1612 & Before .....	4147716		6778BR
Transaxle .....	4143636		6807BR
<b>942311; 942311G</b>			
Deck Drive .....	4147716		6778BR
Transaxle .....	4143636		6807BR
<b>942313; 942313G</b>			
Deck Drive .....	4143733		6746BR
Transaxle .....	4143636		6807BR
<b>942314G</b>			
Deck Drive .....	4163569		6878BR
Transaxle .....	4143636		6807BR
<b>942315G</b>			
Deck Drive .....	4143733		6746BR
Transaxle .....	4143636		6807BR
<b>942316G</b>			
Deck Drive .....	4163569		6878BR
Transaxle .....	4143636		6807BR
<b>942404F; 942404G; 942405F; 942405G</b>			
Deck Drive .....	4163569		6878BR
Hydro. Drive .....	4143636		6807BR
<b>942406H</b>			
Deck Drive .....	4143733		6746BR
Transaxle .....	4143636		6807BR
<b>942407H; 942407J</b>			
Deck Drive .....	4163569		6878BR
Transaxle .....	4143636		6807BR
<b>942408H</b>			
Deck Drive .....	4168470		6746BR
Transaxle .....	4143636		6807BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOBCAT - Continued</b>			
<b>942409J</b>			
Deck Drive .....	4163569		6878BR
Transaxle .....	4143636		6807BR
<b>942411</b>			
Deck Drive .....	4168470		6746BR
Transaxle .....	4143636		6807BR
<b>942412</b>			
Deck Drive .....	4163569		6878BR
Transaxle .....	4143636		6807BR
<b>942500G; 942501G; 942501J</b>			
Deck Drive .....	4165619		6892BR
Hydro. Drive .....	4157920		6891BR
<b>942502G; 942502J; 942504G; 942504J;</b> <b>942505G</b>			
Deck Drive .....	4165618		6893BR
Hydro. Drive .....	4157920		6891BR
<b>942506G; 942506J</b>			
Deck Drive .....	4165619		6892BR
Hydro. Drive .....	4157920		6891BR
<b>942507G; 942507J</b>			
Deck Drive .....	4165618		6893BR
Hydro. Drive .....	4157920		6891BR
<b>942508G; 942508J</b>			
Deck Drive .....	4165645		6920BR
Hydro. Drive .....	4157920		6891BR
<b>942509G</b>			
Deck Drive; W/61" Deck .....	4165644		7032BR
Hydro. Drive .....	4157920		6891BR
<b>942509J</b>			
Deck Drive .....	4165644		7032BR
Hydro. Drive .....	4157920		6891BR
<b>942509K</b>			
Deck Drive .....	4169714		7032BR
Hydro. Drive .....	4157920		6891BR
<b>942510G</b>			
Deck Drive; W/61" Deck .....	4165644		7032BR
Hydro. Drive .....	4157920		6891BR
<b>942510J</b>			
Deck Drive .....	4165644		7032BR
Hydro. Drive .....	4157920		6891BR
<b>942510K</b>			
Deck Drive .....	4169714		7032BR
Hydro. Drive .....	4157920		6891BR
<b>942511G</b>			
Deck Drive; W/72" Deck .....	4165617		7033BR
Hydro. Drive .....	4157920		6891BR
<b>942511J; 942511K</b>			
Deck Drive .....	4165617		7033BR
Hydro. Drive .....	4157920		6891BR
<b>942512G</b>			
Deck Drive .....	4165644		7032BR
Hydro. Drive .....	4157920		6891BR
<b>942513G</b>			
Deck Drive .....	4165617		7033BR
Hydro. Drive .....	4157920		6891BR
<b>942514G; 942514J</b>			
Deck Drive .....	4165618		6893BR
Hydro. Drive .....	4161304		6861BR
<b>942514K</b>			
Hydro. Drive .....	4161304		6861BR
<b>942515G; 942515J</b>			
Deck Drive .....	4165618		6893BR
Hydro. Drive .....	4161304		6861BR
<b>942516G; 942516J</b>			
Deck Drive .....	4165645		6920BR
Hydro. Drive .....	4161304		6861BR





Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOBCAT - Continued</b>				<b>BOBCAT - Continued</b>			
<b>942517G; 942517J</b>				<b>942604 – Continued</b>			
Deck Drive .....	4143733		6746BR	Transaxle .....	4168621		7013BR
Hydro. Drive .....	4157920		6891BR				
<b>942518G; 942519G; 942519J</b>				<b>942605</b>			
Deck Drive .....	4165645		6920BR	Deck Drive .....	4169640		6892BR
Hydro. Drive .....	4161304		6861BR	Transaxle .....	4168621		7013BR
<b>942519K</b>				<b>942606</b>			
Hydro. Drive .....	4161304		6861BR	Deck Drive .....	4163569		6878BR
				Transaxle .....	4168621		7013BR
<b>942520H; 942520J</b>				<b>942607</b>			
Deck Drive .....	4165619		6892BR	Transaxle .....	4168621		7013BR
Hydro. Drive .....	4157920		6891BR				
<b>942520K</b>				<b>942610</b>			
Deck Drive .....	4169640		6892BR	Deck Drive .....	4169566		6692BR
Hydro. Drive .....	4157920		6891BR	Transaxle .....	4143636		6807BR
<b>942521H; 942521J</b>				<b>942611</b>			
Deck Drive .....	4165618		6893BR	Deck Drive .....	4169640		6892BR
Hydro. Drive .....	4157920		6891BR	Transaxle .....	4143636		6807BR
<b>942521K</b>				<b>942612</b>			
Hydro. Drive .....	4157920		6891BR	Deck Drive .....	4163569		6878BR
				Transaxle .....	4143636		6807BR
<b>942522J</b>				<b>942620</b>			
Deck Drive .....	4165619		6892BR	Deck Drive .....	4169566		6692BR
Hydro. Drive .....	4157920		6891BR	Transaxle .....	4143636		6807BR
<b>942523J</b>				<b>942621</b>			
Deck Drive .....	4165618		6893BR	Deck Drive .....	4169640		6892BR
Hydro. Drive .....	4157920		6891BR	Transaxle .....	4143636		6807BR
<b>942525J</b>				<b>942622</b>			
Deck Drive .....	4165619		6892BR	Deck Drive .....	4163569		6878BR
Hydro. Drive .....	4157920		6891BR	Transaxle .....	4143636		6807BR
<b>942526J</b>				<b>942630</b>			
Deck Drive .....	4165618		6893BR	Deck Drive .....	4169566		6692BR
Hydro. Drive .....	4157920		6891BR	Transaxle .....	4143636		6807BR
<b>942529J; 942529K</b>				<b>942631</b>			
Deck Drive .....	4169640		6892BR	Deck Drive .....	4169640		6892BR
Hydro. Drive .....	4161304		6861BR	Transaxle .....	4143636		6807BR
<b>942532; 942532K</b>				<b>942632</b>			
Deck Drive .....	4169640		6892BR	Deck Drive .....	4163569		6878BR
Hydro. Drive .....	4157920		6891BR	Transaxle .....	4143636		6807BR
<b>942533; 942533K</b>				<b>Eng. To Hyd. Pump</b>			
Hydro. Drive .....	4157920		6891BR	Starter/Gen. ....	7540169	7355	
<b>942534K</b>				<b>Motor 180</b>			
Deck Drive .....	4169640		6892BR	Front Reel .....	108025		6952
Hydro. Drive .....	4157920		6891BR	Rear Reel .....	108024		6946
<b>942535K</b>				<b>Motor 213D</b>			
Hydro. Drive .....	4157920		6891BR	W.P. & Alt. ....	FM355	7355	
<b>942536K</b>				<b>Motor 350D</b>			
Deck Drive .....	4169640		6892BR	Fan & Alt. ....	REMF6410	9420	9420HD
Hydro. Drive .....	4157920		6891BR				
<b>942537K; 942542; 942543</b>				<b>T16K</b>			
Hydro. Drive .....	4157920		6891BR	Traction .....	38017		6944
<b>942545</b>				<b>T22D</b>			
Hydro. Drive .....	4161304		6861BR	Fan & Idler .....			AX34
				W.P. & Alt. ....	REMF1370	7370	
<b>942546; 942547</b>				<b>T24N; T188</b>			
Deck Drive .....	4169640		6892BR	Eng. To J.S. ....			3V375
Hydro. Drive .....	4157920		6891BR				
<b>942600</b>				<b>T1648</b>			
Deck Drive .....	4168384		7016BR	Eng. To Trans. ....	118071	2350	6835
Transaxle .....	4168621		7013BR				
<b>942601</b>				<b>TW28CG</b>			
Deck Drive .....	4168130		7017BR	Fan & Idler .....		7300	
Transaxle .....	4168621		7013BR	Fan To Alt.; W/40A. Alt. ....	48519	7450	
<b>942602</b>				<b>BOLENS</b>			
Deck Drive .....	4163569		6878BR	<b>13AM662F163</b>			
Transaxle .....	4168621		7013BR	Deck Drive .....	7540329A		6630BR
<b>942604</b>				Drive - Lower .....	75404001A		6969
Deck Drive .....	4169566		6692BR	Drive - Upper .....	75404002		6618BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS - Continued</b>			
<b>13AN863G163; 13AO683G163</b>			
Deck Drive .....	7540371A		6402BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	75404002		6618BR
<b>13AQ683G163; 13AQ683H163</b>			
Drive .....	75404002		6618BR
<b>13W1762F065; 13WC762F065; 13WC762F265</b>			
Deck Drive .....	954-04062		6774BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-0241A		6494BR
<b>70S</b>			
Primary .....	1720131		6844
<b>160-01; 161-01</b>			
Eng. To Versamatic .....	1720131		6844
Gen. ....	1713533		6734
P.T.O. ....			6833
Versamatic To Drive .....	1715942		6847
<b>164-01; 165-01</b>			
Eng. To Versamatic .....	1720131		6844
Gen. ....	1713533		6734
P.T.O. ....	1720726		6833
Versamatic To Drive .....	1715942		6847
<b>166-01; 166-02</b>			
Differential .....			6846
Gen. ....	1713533		6734
P.T.O. ....	1720726		6833
<b>171-01</b>			
Drive .....			6835
P.T.O. ....	1713714		6843
<b>172-01</b>			
Drive .....			6835
Gen. ....	1713533		6734
P.T.O. ....	1713714		6843
<b>190-01</b>			
Gen. ....			6832
P.T.O. ....	1716571		6834
<b>191-01; 191-02</b>			
Gen. ....			6832
P.T.O. ....			6943
<b>192-01; 192-02; 193-01</b>			
Gen. ....			6832
P.T.O. ....	1716571		6834
<b>194-01</b>			
Drive; W/30" Belt O.C. ....			6830
Gen. ....			6832
<b>197-01; 197-02; 197-03; 198-01; 198-02</b>			
Drive .....			6832
Gen. ....	1711844		6836
<b>248-047</b>			
P.T.O. ....	1726701		6877
<b>510-01; 510-02</b>			
Drive .....	1722238	2650	6865
P.T.O. ....	1722258		6831
<b>528</b>			
Blade; W/64" Belt O.C. ....	1736248		6864
Blade; W/65" Belt O.C. ....	1738496		6865
Trans. ....	1731719		6851
<b>610-01; 610-02; 613-01; 613-02; 613-04</b>			
Drive .....	1722238	2650	6865
P.T.O. ....	1722258		6831
<b>628</b>			
Trans. ....	1731719		6851
<b>728</b>			
Blade .....			6868
Trans. ....	1724261		6851
<b>730-01; 733-01</b>			
Eng. To Versamatic .....	1720131		6844

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS - Continued</b>			
<b>730-01; 733-01 - Continued</b>			
Gen. ....	1713533		6734
P.T.O. ....	1720726		6833
Versamatic To Drive .....	1715942		6847
<b>736-01</b>			
Differential .....			6846
Gen. ....	1713533		6734
P.T.O. ....	1720726		6833
<b>770</b>			
Eng. To Versamatic .....	1720131		6844
Gen. ....	1713533		6734
P.T.O. ....	1720726		6833
Versamatic To Drive .....	1715942		6847
<b>775</b>			
Differential .....			6846
Gen. ....	1713533		6734
P.T.O. ....	1720726		6833
<b>812</b>			
Drive .....	1737347		6869
P.T.O. ....	1732582		6831
Trans. ....	1741135		6871
<b>813; 813-01; 813-03</b>			
Drive .....	1722238	2650	6865
P.T.O.; Ser. No. 0400101 Thru 0599999 .....	1722258		6831
P.T.O.; Ser. No. 0600101 & After .....	1732582		6831
<b>814</b>			
Drive .....	1732726		6871
P.T.O. ....	1732582		6831
<b>828; 829</b>			
Blade .....			6868
Trans.; Ser. No. 0100101 Thru 0199999 .....	1724261		6851
Trans.; Ser. No. 0200101 & After .....	1731719		6851
<b>830; 831</b>			
Blade; W/30" Mower; Ser. No. SNO399999 & Before .....	1722238	2650	6865
Blade; W/30" Mower; Ser. No. SNO400101 & After .....	1738511	2660	6866
Drive .....	1731719	2510	6851
<b>853-01; 853-02; 853-03</b>			
Eng. ....			6935
Gen. ....	1713533		6734
P.T.O. ....			6944
<b>855</b>			
Drive; Ser. No. 0300101 & After .....			6835
P.T.O. ....	1725603		6843
<b>909-01; 910; 910-01; 910-02; 910-03; 911; 911-01; 911-02; 912-02; 914</b>			
P.T.O. ....	1715942		6847
Trans. ....			6838
<b>914-01; 914-02; 915; 915-01; 915-02; 915-03</b>			
P.T.O. ....	1715942		6847
Trans. ....			6838
<b>930</b>			
Gen. ....	1716161		6831
High Speed Drive .....			3V250
Low Speed Drive .....			3V315
P.T.O. ....	1715614		6728
<b>930-01; 930-02</b>			
High Speed Drive .....			3V250
Low Speed Drive .....	1715612		3V315
P.T.O. ....	1715614		6728
<b>931</b>			
Gen. ....	1716161		6831
High Speed Drive .....	1719269		6725
Low Speed Drive .....			3V315
P.T.O. ....	1715614		6728
<b>931-01; 931-02</b>			
P.T.O. ....	1715614		6728



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS - Continued</b>			
<b>933M; 936M</b>			
Eng. To J.S. ....	9585005300		6855
Eng. To Trans. ....	9585005000		6837
<b>960-01; 960-02</b>			
P.T.O. ....			6858
<b>1000</b>			
Drive ..... 1716571			6834
Gen. ....			6832
<b>1011GM; 1011HM</b>			
Eng. To Deck ..... 213676			6885
<b>1050</b>			
Drive ..... 1716571			6834
Gen. ....			6832
<b>1053</b>			
Drive; Ser. No. 0300101 & After .....			6835
P.T.O. .... 1725603			6843
<b>1053-01; 1053-02; 1054-01; 1054-03; 1054-04</b>			
Drive ..... 1716571			6834
Gen. ....			6832
<b>1055</b>			
Drive; Ser. No. 0300101 & After .....			6835
P.T.O. .... 1725603			6843
<b>1058</b>			
P.T.O. .... 1726701			6877
<b>1060</b>			
Drive ..... 1726701			6847
P.T.O. ....			6877
<b>1068</b>			
P.T.O. .... 1726701			6877
<b>1113</b>			
Drive ..... 1732726			6871
P.T.O. .... 1732582			6831
Trans. .... 1741135			6871
<b>1130</b>			
Blade; Ser. No. SNO399999 & Before .... 1722238	2650		6865
Blade; Ser. No. SNO400101 & After ..... 1738511	2660		6866
Drive ..... 1731719	2510		6851
<b>1134</b>			
Trans. .... 1731719	2510		6851
<b>1136</b>			
Blade ..... 1747938			6896
Trans. .... 1731719			6851
<b>1155</b>			
Drive; Ser. No. 0300101 & After .....			6835
P.T.O. .... 1725603			6843
<b>1160</b>			
Drive ..... 1726701			6847
P.T.O. ....			6877
<b>1253-01; 1253-02; 1254-01; 1254-03; 1254-04; 1254-05; 1254-06</b>			
Drive ..... 1716571			6834
Gen. ....			6832
<b>1255</b>			
P.T.O. .... 1725603			6843
<b>1256-01; 1256-02; 1256-04; 1256-05; 1256-06; 1256-07; 1257-01</b>			
Drive ..... 1726701			6830
Gen. ....			6832
<b>1258</b>			
P.T.O. .... 1726701			6877
<b>1261</b>			
Drive ..... 1726701			6847
<b>1349</b>			
Belt ..... 1724943			A136

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS - Continued</b>			
<b>1400</b>			
Trans. ....			6847
<b>1453</b>			
Drive ..... 1716571			6834
<b>1455</b>			
Drive ..... 1711844			6832
Gen. ....			6836
<b>1456</b>			
Drive ..... 1711844			6830
<b>1458</b>			
P.T.O. .... 1726701			6877
<b>1461; 1463</b>			
Drive ..... 1711844			6847
<b>1476-01; 1477-01</b>			
Belt; W/32" Deck ..... 1711844			6875
Drive ..... 1711844			6832
Gen. ....			6836
<b>1556-01; 1556-02; 1556-03; 1656</b>			
Drive ..... 1711844			6830
<b>1658</b>			
P.T.O. .... 1726701			6877
<b>1661</b>			
Drive ..... 1726701			6847
P.T.O. ....			6877
<b>1666</b>			
P.T.O. .... 1726701			6836
<b>1858</b>			
P.T.O. .... 1726701			6877
<b>1886-01; 1886-03; 1886-04; 1886S-05; 1886S-06</b>			
Drive ..... 1726701			6835
<b>1966</b>			
P.T.O. .... 1726701			6836
<b>2086; 2087; 2288; 2289; 2389</b>			
Drive ..... 1726701			6835
<b>6428-01</b>			
Belt; W/24" Rotary Mower ..... 1108466			6833
<b>6466-01; 6466-02</b>			
Blade ..... 1705034			6835
Eng. .... 1705033		2220	6822
<b>6467-01; 8266-01</b>			
Blade ..... 1800367			6833
Drive ..... 1705034			6835
Eng. .... 1705033		2220	6822
<b>8424-01</b>			
Belt; W/24" Rotary Mower ..... 1108466			6833
<b>8426-01</b>			
Blade ..... 1705034			6850
Drive ..... 1705034			6828
Trans. .... 1705034			6835
<b>8436-01</b>			
Blade To Blade; W/36" Rotary Mower .... 1711844			6836
Drive; W/36" Rotary Mower ..... 1705034			6835
Eng.; W/36" Rotary Mower ..... 1705033		2220	6822
Eng. To Blade; W/36" Rotary Mower ..... 1711845		3440	6944
<b>8524-01</b>			
Belt; W/24" Rotary Mower ..... 1108466			6833
<b>8526-01</b>			
Blade ..... 1711844			6850
Drive ..... 1711844			6828
<b>8536-01</b>			
Blade To Blade; W/36" Rotary Mower .... 1711844			6836
Drive; W/36" Rotary Mower ..... 1711916		2390	6839
Eng.; W/36" Rotary Mower ..... 1705033		2220	6822
Eng. To Blade; W/36" Rotary Mower ..... 1711845		3440	6944

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS - Continued</b>			
<b>8624-01</b> Belt; W/24" Rotary Mower .....			6833
<b>8626-01</b> Blade; W/26" Rotary Mower ..... 1714106 Drive; W/26" Rotary Mower ..... 1714107		2210	6821 6846
<b>8724-01; 8724-02; 8724-03; 8725-01</b> Belt; W/24" Rotary Mower .....			6833
<b>8726-01</b> Eng. To Blade; W/26" Rotary Mower ..... 1714285 Eng. To Drive; W/26" Rotary Mower .....		2230 2480	6823 6848
<b>8726-02; 8726-03; 8727-01; 8728-01</b> Belt; W/30" Rear Eng.; W/26" Rotary Mower ..... 1722238 Blade; W/26" Rotary Mower ..... Trans.; W/26" Rotary Mower .....		2650 1230 2480	6865 6723 6848
<b>15550</b> Belt; W/30" Deck .....			3VX670
<b>15570</b> Belt; W/42" Deck ..... 1728133 Drive ..... 1743876			6892 6898
<b>17350</b> Belt; W/48" Deck ..... 1724943			A136
<b>18001; 18006</b> Belt; W/32" Deck .....			6875
<b>18048</b> Belt; W/48" Deck ..... 1718653			A128
<b>18335</b> Belt; W/42" Deck ..... 1728133 Drive; W/B. & S. Eng. .... 1741576 Drive; W/Tecumseh Eng. .... 1726701			6892 6881 6877
<b>18336</b> Blade; W/100" Belt O.C. .... 1736903 Drive; W/B. & S. Eng. .... 1741577 Drive; W/Tecumseh Eng. .... 1739080			68100 6883 6879
<b>18338</b> Belt; W/48" Deck ..... 1737187 Drive; W/B. & S. Eng. .... 1739080 Drive; W/Tecumseh Eng. .... 1728133			6895 6879 6892
<b>18415; 18416; 18417; 18418</b> Belt; W/38" Deck .....			6875
<b>18420; 18421; 18423</b> Belt; W/42" Deck ..... 1185651			A112
<b>18440</b> Belt; W/32" Deck ..... 1713853			6857
<b>18441; 18442</b> Belt; W/32" Deck .....			6870
<b>18445</b> Belt; W/32" Deck ..... 1713853			6857
<b>18446</b> Belt; W/32" Deck; W/70" Belt O.C. .... Belt; W/32" Deck; W/75" Belt O.C. ....			6870 6875
<b>18449</b> Belt; W/32" Deck .....			6870
<b>18457</b> Belt; W/42" Deck ..... 1185651			A112
<b>19101</b> Belt; W/28" Deck ..... 1715213			6861
<b>19102</b> Belt; W/38" Deck .....			6875
<b>19107</b> Belt; W/28" Deck ..... 1715213			6861
<b>19108</b> Belt; W/32" Deck .....			6875

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS - Continued</b>			
<b>19342</b> Belt; W/42" Deck ..... 1185651			A112
<b>50042S</b> Deck ..... 1746823			68105
<b>50048R; 50048S</b> Belt; W/48" Deck ..... 1724943			A136
<b>Grounds Keeper</b> Primary P.T.O. .... 1717120 Pump & Gen. .... Wing Mower .....			6844 6858 6860
<b>LT11</b> Eng. To J.S. .... 1732582 Eng. To Trans. .... 1732726			6831 6871
<b>QS16 1660</b> Drive ..... 1724729			②6835
<b>QT17 1660</b> P.T.O. ....			6836
<b>BUNTON</b>			
<b>642201</b> Blade Drive ..... 128110 P.T.O. .... 2720815 Traction ..... 2188128			6615BR 6806BR 6530BR
<b>642203; 642204</b> Blade Drive ..... 2188176 P.T.O. .... 2188175 Traction ..... 2188128			6574BR 6721BR 6530BR
<b>642206; 642207</b> Blade Drive ..... 128003 P.T.O. .... 2188134 Traction ..... 2188128			6485BR 6480BR 6530BR
<b>642211</b> Blade Drive ..... 2188176 P.T.O. .... 2188175 Traction ..... 2188128			6574BR 6721BR 6530BR
<b>642211A</b> Blade Drive ..... 2188176 P.T.O. .... 2720815 Traction ..... 2188128			6574BR 6806BR 6530BR
<b>642213; 642215</b> Blade Drive; W/52" Deck ..... 2188176 Blade Drive; W/61" Deck ..... 128003 P.T.O.; W/52" Deck ..... 2188175 P.T.O.; W/61" Deck ..... 2188134 Traction ..... 2188128			6574BR 6485BR 6721BR 6480BR 6530BR
<b>642218F</b> Blade Drive ..... 2188176 P.T.O. .... 2720815 Traction ..... 4162583			6574BR 6806BR 6890BR
<b>642219F</b> Blade Drive ..... 128003 P.T.O. .... 2188134 Traction ..... 4162583			6485BR 6480BR 6890BR
<b>642220; 642220A</b> Blade Drive ..... 128110 P.T.O. .... 2720815 Traction ..... 2188128			6615BR 6806BR 6530BR
<b>642221; 642221A</b> Blade Drive ..... 2188176 P.T.O. .... 2188175 Traction ..... 2188128			6574BR 6721BR 6530BR
<b>642221F</b> Blade Drive ..... 2188176 P.T.O. .... 2720815 Traction ..... 4162583			6574BR 6806BR 6890BR
<b>642222; 642222A</b> Blade Drive ..... 2188176 P.T.O. .... 2188175 Traction ..... 2188128			6574BR 6721BR 6530BR

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BUNTON - Continued</b>				<b>BUNTON - Continued</b>			
<b>642223; 642223A</b>				<b>642242F - Continued</b>			
Blade Drive .....	128003		6485BR	Traction .....	4161305		6889BR
P.T.O. ....	2188134		6480BR	<b>642243E</b>			
Traction .....	2188128		6530BR	Blade Drive .....	128003		6485BR
<b>642225</b>				Pump Drive .....	4157920		6891BR
Blade Drive .....	2188176		6574BR	<b>642244F</b>			
P.T.O. ....	2188134		6480BR	Blade Drive .....	2188176		6574BR
<b>642226</b>				P.T.O. ....	2720815		6806BR
Blade Drive .....	128003		6485BR	Traction .....	4162583		6890BR
<b>642227; 642227A</b>				<b>642245E</b>			
Blade Drive .....	2188176		6574BR	Blade Drive .....	4135683		6804BR
P.T.O. ....	2188175		6721BR	<b>642245F</b>			
Traction .....	2188128		6530BR	Blade Drive .....	128003		6485BR
<b>642228; 642228A</b>				Traction .....	4161304		6861BR
Blade Drive .....	128003		6485BR	<b>642246F</b>			
P.T.O. ....	2188134		6480BR	Blade .....	128003		6485BR
Traction .....	2188128		6530BR	P.T.O. ....	2188134		6480BR
<b>642230; 642230A</b>				Traction .....	4161305		6889BR
Blade Drive .....	128003		6485BR	<b>642247F</b>			
P.T.O. ....	2722224		6857BR	Blade Drive .....	4135683		6804BR
Traction .....	2188128		6530BR	P.T.O. ....	2722554		6805BR
<b>642231</b>				Traction .....	4161305		6889BR
P.T.O. ....	2722554		6805BR	<b>642248F</b>			
Traction .....	2188128		6530BR	Blade Drive .....	2188176		6574BR
<b>642231A</b>				P.T.O. ....	2720815		6806BR
Blade Drive .....	4135683		6804BR	Traction .....	4162583		6890BR
P.T.O. ....	2722554		6805BR	<b>642249F</b>			
Traction .....	2188128		6530BR	Blade Drive .....	128003		6485BR
<b>642233; 642233A</b>				P.T.O. ....	2188134		6480BR
Blade Drive .....	128003		6485BR	Traction .....	4162583		6890BR
P.T.O. ....	2188134		6480BR	<b>642290E; 642291E; 642291F</b>			
Traction .....	2188128		6530BR	Deck Drive .....	4144212		6981BR
<b>642233F</b>				Transaxle .....	4143636		6807BR
Blade Drive .....	128003		6485BR	<b>642293E</b>			
P.T.O. ....	2188134		6480BR	Deck Drive .....	4147716		6778BR
Traction .....	4162583		6890BR	Transaxle .....	4143636		6807BR
<b>642237A</b>				<b>642295E; 642295F</b>			
Blade Drive .....	128003		6485BR	Deck Drive .....	4147095		6759BR
P.T.O. ....	2188134		6480BR	Transaxle .....	4143636		6807BR
Traction .....	2188128		6530BR	<b>642296E; 642296F</b>			
<b>642237F</b>				Deck Drive .....	4143733		6746BR
Blade Drive .....	128003		6485BR	Transaxle .....	4143636		6807BR
P.T.O. ....	2188134		6480BR	<b>642311F</b>			
Traction .....	4162583		6890BR	Deck Drive .....	4147716		6778BR
<b>642238A</b>				Transaxle .....	4143636		6807BR
Blade Drive .....	128003		6485BR	<b>642313F</b>			
P.T.O. ....	2722224		6857BR	Deck Drive .....	4143733		6746BR
Traction .....	2188128		6530BR	Transaxle .....	4143636		6807BR
<b>642239A</b>				<b>642404F</b>			
Blade Drive .....	4135683		6804BR	Deck Drive .....	4163569		6878BR
P.T.O. ....	2722554		6805BR	Transaxle .....	4143636		6807BR
Traction .....	2188128		6530BR	<b>BURNS</b>			
<b>642240E</b>				<b>40-724; 40-725; 40-726; 40-727</b>			
Blade Drive .....	2188176		6574BR	Drive .....	11144		6835
P.T.O. ....	2720815		6806BR	Trans. ....			6852
<b>642241E</b>				<b>40-942; 40-949; 40-950</b>			
Blade Drive .....	128003		6485BR	Trans. ....			6852
P.T.O. ....	2722224		6857BR	<b>815</b>			
<b>642241F</b>				Blade .....			6854
Blade Drive .....	128003		6485BR	Traction .....	13487	2370	
P.T.O. ....	2188134		6480BR	<b>816</b>			
Traction .....	4161305		6889BR	Blade .....	14365		A49
<b>642242E</b>				<b>817; 818</b>			
Blade Drive .....	4135683		6804BR	Eng. To Blade .....	13560		6859
P.T.O. ....	2722554		6805BR	Traction .....	13487	2370	
<b>642242F</b>							
Blade Drive .....	4135683		6804BR				
P.T.O. ....	2722554		6805BR				

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BURNS - Continued</b>			
<b>850</b>			
Drive .....	10923		6830
Traction .....	10897		6851
<b>851; 851X</b>		2370	6830
Eng. To Deck .....	10923		
Traction .....	13487		
<b>852</b>			
Drive .....	10923		6830
Traction .....	10897		6851
<b>855</b>		2370	6960
Eng. To Deck .....	17518		
Traction .....	13487		
<b>859</b>			
Drive .....	10923		6830
Traction .....	10897		6851
<b>6087914</b>			6830
Drive .....	4638		
<b>6088314</b>			
Deck .....	10923		6830
Traction .....	10897		6851
<b>B60; B60E</b>			6837
Eng. To Shaft .....	7080		
<b>B90E</b>		3340	②3V250 6934
Belt; W/36" Rotary Mower .....	7087		
Eng. To Shaft .....	7062		
<b>M60; M60E</b>			6837
Eng. To Shaft .....	7080		
<b>M90E</b>		3340	②3V250 6934
Belt; W/36" Rotary Mower .....	7087		
Eng. To Shaft .....	7062		
<b>BUSH HOG</b>			
<b>CZ2149; CZ2349</b>			6599BR 6799BR
Deck Drive .....	88667		
Pump .....	50027563		
<b>CZ2355; CZ2555</b>			6800BR 6799BR
Deck Drive .....	1550119		
Pump .....	50027563		
<b>CZ2561</b>			6598BR 6799BR
Deck Drive .....	50047108		
Pump .....	50027563		
<b>EC2561KH</b>			6769BR 6780BR
Deck Drive .....	94898		
Pump Drive .....	50068022		
<b>EC2655KW</b>			6746BR 6780BR
Deck Drive .....	1550111		
Pump Drive .....	50068022		
<b>EC2661KW</b>			6769BR 6780BR
Deck Drive .....	94898		
Pump Drive .....	50068022		
<b>ES1744</b>			A67 6976BR
Pump; 2007 & Older .....	50045945		
Pump; 2008 & Newer .....	50049635		
<b>ES1844; ES1852</b>			A67
Pump .....	50045945		
<b>ES2044</b>			A67 6976BR
Pump; 2007 & Older .....	50045945		
Pump; 2008 & Newer .....	50049635		
<b>ES2052</b>			6800BR A67 6976BR
Deck Drive; 2008 & Newer .....	1550119		
Pump; 2007 & Older .....	50045945		
Pump; 2008 & Newer .....	50049635		
<b>ES2244</b>			6976BR
Pump Drive .....	50049635		
<b>ES2252; ES2352; ES2452</b>			6800BR
Deck Drive .....	1550119		

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BUSH HOG - Continued</b>			
<b>ES2252; ES2352; ES2452 - Continued</b>			6976BR
Pump Drive .....	50049635		
<b>GT41</b>			6946
Eng. To Blade .....	65482		
<b>HD12</b>			3V250
P.T.O. ....	S2954		
<b>HS1736</b>			6650BR
Deck Drive .....	50023377		
<b>HS1742</b>			6688BR
Deck Drive .....	50055781		
<b>HS1836</b>			6650BR
Deck Drive .....	50023377		
<b>HS1842; HS2042</b>			6688BR
Deck Drive .....	50055781		
<b>JB1</b>			6935
P.T.O. ....	S4763		
<b>M2254</b>			6732BR 6799BR
Deck Drive .....	50027565		
Pump .....	50027563		
<b>M2255; M2260</b>			6799BR
Pump .....	50027563		
<b>M2261</b>			6801BR 6799BR
Deck Drive .....	50034723		
Pump .....	50027563		
<b>M2354</b>			6732BR 6799BR
Deck Drive .....	50027565		
Pump .....	50027563		
<b>M2355; M2355A; M2360</b>			6799BR
Pump .....	50027563		
<b>M2361</b>			6801BR 6799BR
Deck Drive .....	50034723		
Pump .....	50027563		
<b>M2554</b>			6732BR 6799BR
Deck Drive .....	50027565		
Pump .....	50027563		
<b>M2555; M2555K; M2560</b>			6799BR
Pump .....	50027563		
<b>M2561; M2561K; M2661</b>			6801BR 6799BR
Deck Drive .....	50034723		
Pump .....	50027563		
<b>M2672</b>			6761BR 6799BR
Deck Drive .....	50027564		
Pump .....	50027563		
<b>M2673</b>			6799BR
Pump .....	50027563		
<b>M2761</b>			6801BR 6799BR
Deck Drive .....	50034723		
Pump .....	50027563		
<b>M4420PS</b>			6976BR
Pump Drive .....	50049635		
<b>M5220KT; M5225CT</b>			6800BR 6976BR
Deck Drive .....	1550119		
Pump Drive .....	50049635		
<b>P5525CT</b>			6746BR 6780BR
Deck Drive .....	1550111		
Pump Drive .....	50068022		
<b>P6124FS; P6126KP; P6127CT</b>			6769BR 6780BR
Deck Drive .....	94898		
Pump Drive .....	50068022		
<b>PZ2555</b>			6800BR 6799BR
Deck Drive .....	1550119		
Pump .....	50027563		
<b>PZ2561; PZ2661</b>			6598BR
Deck Drive .....	50047108		

②Two Required





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BUSH HOG - Continued</b>			
<b>PZ2561; PZ2661 - Continued</b>			
Pump .....	50027563		6799BR
<b>PZ2755</b>			
Deck Drive .....	1550119	6800BR	
Pump .....	50027563	6799BR	
<b>PZ2861</b>			
Deck Drive .....	50047108	6598BR	
Pump .....	50027563	6799BR	
<b>PZ2873</b>			
Deck Drive .....	50047109	7031BR	
Pump .....	50027563	6799BR	
<b>PZ3061</b>			
Deck Drive .....	50047108	6598BR	
Pump .....	50027563	6799BR	
<b>PZ3073</b>			
Deck Drive .....	50047109	7031BR	
Pump .....	50027563	6799BR	
<b>PZ6127CV; PZ6127FX</b>			
Deck Drive .....	50047108	6598BR	
Pump Drive .....	50070699	6630BR	
<b>PZ7326VG; PZ7327CV; PZ7327FX</b>			
Deck Drive .....	50047109	7031BR	
Pump Drive .....	50070699	6630BR	
<b>VE Series; YR Series</b>			
Implement Clutch .....	S1669	6836	
<b>ZT180; ZT220-W; ZT230</b>			
Deck Drive; W/48" Deck .....	96814	6665BR	
<b>CANADA</b>			
<b>52094</b>			
Deck .....	213676	6885	
<b>CANADIAN TIRE</b>			
<b>115-460-515</b>			
Blade .....	7540151	6967	
Eng. To Variator .....	7540138	6950	
Variator To Trans. ....	7540136	6931	
<b>CASE, J.I.</b>			
<b>80</b>			
Blade .....	C24349	6860	
Drive .....	C24342	6836	
<b>107</b>			
Eng. ....	C15370	6863	
<b>108; 110</b>			
P.T.O. ....	C15552	6833	
Trans. ....	C18634	6882	
<b>117</b>			
P.T.O. ....	C15552	6833	
<b>120</b>			
Deck; W/71" Belt O.C. ....	C10769	3VX710	
Deck; W/75" Belt O.C. ....	C23811	3V750	
Drive; W/38" Deck .....	C14980	6761	
Gen. ....		6735	
P.T.O. ....	C10507	3V300	
<b>130</b>			
Blade .....	C11945	6882	
Deck; W/C-38 Drive .....	C12493	6841	
Deck; W/C-44 Drive .....	C12494	6842	
Mower; W/C-38 Drive .....	C12491	6857	
Mower; W/C-44 Drive .....	C12492	6858	
Starter/Gen. ....		6735	
<b>150</b>			
Deck; W/71" Belt O.C. ....	C10769	3VX710	
Deck; W/75" Belt O.C. ....	C23811	3V750	
Drive; W/38" Deck .....	C14980	6761	
Gen. ....		6735	
P.T.O. ....	C10507	3V300	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CASE, J.I. - Continued</b>			
<b>155</b>			
Blade .....	C23811		3V750
Gen. ....			6735
P.T.O. ....	C10507		3V300
<b>180</b>			
Blade .....	C11945		6882
Mower; W/C-44R Drive .....	C11988		6956
Starter/Gen. ....			6735
<b>190</b>			
Gen. ....			6735
P.T.O. ....	C10507		3V300
<b>195</b>			
Blade .....	C23811		3V750
Gen. ....			6735
P.T.O. ....	C10507		3V300
<b>210</b>			
Clutch .....	C18919		6831
Gen. ....	C14345		6734
Traction .....	C18918		6868
<b>220; 222; 224</b>			
Drive .....	C14345		6734
Gen. ....	C23902	7335	
P.T.O. ....	C14116		6841
<b>235; 255</b>			
Fan & Alt. ....	MD007528	7370	
<b>265</b>			
Fan & Alt. ....	MB041704	7390	
<b>442</b>			
Drive .....	C14345		6734
Gen. ....	C23902	7335	
P.T.O. ....	C14116		6841
<b>444</b>			
Drive; Ser. No. 9488 & After .....	C23359		6871
Drive; W/34" Belt O.C. ....	C14345		6734
Gen. ....	C23902	7335	
P.T.O. ....	C14116		6841
<b>644; 646</b>			
Gen. ....	9744750	7335	
<b>Colt 2110; Colt 2310</b>			
Deck; W/71" Belt O.C. ....	C10769		3VX710
Deck; W/75" Belt O.C. ....	C23811		3V750
Drive; W/38" Deck .....	C14980		6761
<b>Colt 2510; Colt 2712</b>			
Belt; W/44" Deck .....	C23811		3V750
<b>Colt Delux</b>			
Deck; W/C-38 Drive .....	C12493		6841
Deck; W/C-44 Drive .....	C12494		6842
Mower; W/C-38 Drive .....	C12491		6857
Mower; W/C-44 Drive .....	C12492		6858
<b>Colt Rancher</b>			
Mower; W/C-44R Drive .....	C11988		6956
<b>Super 7; Super 9</b>			
Deck; W/C-38 Drive .....	C12493		6841
Deck; W/C-44 Drive .....	C12494		6842
Mower; W/C-38 Drive .....	C12491		6857
Mower; W/C-44 Drive .....	C12492		6858
<b>CASTLE GARDEN</b>			
<b>TCP 12.5/102</b>			
P.T.O. ....	B55		6958
<b>TCP 16/122</b>			
P.T.O. ....	B54		6957
Trans. ....			6862
<b>CHAMPION</b>			
<b>LT12 30" Deck</b>			
Deck .....	106085X		6672BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CHETECH</b>				<b>COAST TO COAST - Continued</b>			
<b>Groundforce 104</b>				<b>134-504; 134-506 - Continued</b>			
Hyd. Pump; W/16 H.P. Eng. ....	2300	2300	6830	Secondary Variator .....	7540240		6511BR
<b>PUG</b>				<b>134-585</b>			
Hyd. Pump; W/Kohler 20 H.P. Eng. ....		2350	6835	Drive; W/28" Belt O.C. ....	7540157		6928
<b>Taskforce 200</b>				Drive; W/31" Belt O.C. ....	7540136		6931
Hyd. Pump; W/18 H.P. Eng. ....		2340	6834	<b>135-340; 135-360</b>			
<b>COAST TO COAST</b>				Blade .....	7540935	2310	6831
<b>31-435</b>				Trans. ....	7540936		6847
Blade .....	7540127		6966	<b>135-380</b>			
Drive .....	7540136		6931	Blade .....	7540935	2310	6831
Variable Speed .....	7540135		6925	Trans. ....	7540108	2460	6846
<b>45-0246</b>				<b>135-525</b>			
Blade .....	7540145		6488BR	Blade .....	7540195		6854
Trans. ....	7540266		6775BR	Trans. ....	7540198		6451BR
<b>130-415</b>				<b>136-390</b>			
Blade .....	7540147	3520	6952	Blade .....	7540935	2310	6831
Drive .....	7540135		6925	Trans. ....	7540111	2450	6845
Variable Speed .....	7540136		6931	<b>143-660; 143-760</b>			
<b>130-420; 130-430</b>				Blade .....	7540184		6852
Blade .....	7540127		6966	Deck .....	7540180		6510BR
Drive .....	7540136		6931	Trans. ....	7540182		6981
Variable Speed .....	7540135		6925	<b>338-3734</b>			
<b>130-460; 130-470</b>				Blade .....	7540147	3520	6952
Blade .....	7540118		6963	Drive .....	7540135		6925
Trans. ....	7540937	3590	6959	Variable Speed .....	7540136		6931
<b>130-480</b>				<b>338-3742</b>			
Blade .....	7540145		6488BR	Blade .....	7540188		6951
Drive; W/31" Belt O.C. ....	7540136		6931	Drive .....	7540101		6517BR
Drive; W/52" Belt O.C. ....	7540147	3520	6952	<b>338-4120; 338-4138; 338-4229</b>			
<b>131-360</b>				Blade .....	7540127		6966
Blade .....	7540107		6830	Drive .....	7540136		6931
Trans. ....	7540936		6847	Variable Speed .....	7540135		6925
<b>131-418</b>				<b>338-4237</b>			
Blade .....	7540147	3520	6952	Blade .....	7540178	3820	6982
Drive .....	7540135		6925	Drive .....	7540185		6849
Variable Speed .....	7540136		6931	<b>338-4435; 338-4443</b>			
<b>131-425</b>				Blade .....	7540138	3500	6950
Blade .....	7540127		6966	Drive .....	7540164	2630	6863
Drive .....	7540136		6931	<b>338-4831; 338-4849; 338-4930; 338-4955</b>			
Variable Speed .....	7540135		6925	Blade .....	7540151		6967
<b>131-480; 131-490</b>				Drive .....	7540127		6966
Blade .....	7540145		6488BR	<b>338-5432; 338-5440</b>			
Drive; W/31" Belt O.C. ....	7540136		6931	Blade .....	7540184		6852
Drive; W/52" Belt O.C. ....	7540147	3520	6952	Deck .....	7540180		6510BR
<b>132-360; 132-365</b>				Gen. ....	7540134	7330	
Blade .....	7540107		6830	Trans. ....	7540182	3810	6981
Trans. ....	7540936		6847	<b>481-0602</b>			
<b>132-390</b>				Blade .....	7540188		6951
Blade .....	7540107		6830	Drive .....	7540101		6517BR
Trans. ....	7540111	2450	6845	<b>481-0628</b>			
<b>132-410</b>				Blade .....	7540127		6966
Blade .....	7540138	3500	6950	Drive .....	7540136		6931
Trans. ....	7540101		6517BR	Variable Speed .....	7540135		6925
<b>132-480; 132-485; 132-495</b>				<b>481-0651</b>			
Blade .....	7540151		6967	Blade .....	7540178	3820	6982
Deck .....	7540138	3500	6950	Trans. ....	7540200		6848
Traction .....	7540136		6931	<b>481-0701</b>			
<b>133-430; 133-435; 134-430</b>				Blade .....	7540138	3500	6950
Blade .....	7540127		6966	Trans. ....	7540198		6451BR
Drive .....	7540136		6931	<b>481-0727; 481-0735</b>			
Variable Speed .....	7540135		6925	Blade .....	7540167		6964
<b>134-480; 134-485</b>				Trans. ....	7540198		6451BR
Blade .....	7540151		6967	<b>481-0750; 481-0776</b>			
Drive .....	7540127		6966	Blade .....	7540151		6967
<b>134-504; 134-506</b>				Trans. ....	7540191		6865
Eng. To Deck .....	7540264		6639BR	<b>481-0784</b>			
Primary Variator .....	7540241		6494BR	Blade .....	7540145		6488BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COAST TO COAST - Continued</b>			
<b>481-0784 - Continued</b>			
Deck .....	7540191		6865
Trans. ....	7540173	3370	6937
<b>481-0792</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>481-0800</b>			
Blade .....	7540145		6488BR
Deck .....	7540191		6865
Trans. ....	7540173	3370	6937
<b>481-0909</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>481-1600</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>481-1626</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>481-1642</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>481-1675</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>481-2202</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>481-2228</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>481-2236; 481-2244</b>			
Blade .....	7540151		6967
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>481-2251; 481-2269</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>481-2277</b>			
Deck .....	7540230		6755BR
Drive .....	7540245		6859
Transaxle .....	7540255		6837
<b>481-2285</b>			
Drive .....	7540245		6859
Transaxle .....	7540244		6840
<b>481-3788</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>481-3929</b>			
Blade; W/44" Deck .....	7540293		6501BR
Eng. To Deck; W/44" Deck .....	7540230		6755BR
Eng. To J.S.; W/44" Deck .....	7540245		6859
J.S. To Trans.; W/44" Deck .....	7540244		6840
<b>841-0800</b>			
Blade .....	7540145		6488BR
Deck .....	7540191		6865
Trans. ....	7540173	3370	6937
<b>948; 971; 973; 974; 6089312; 6089412</b>			
Traction .....	4638		6830
<b>Eight Hundred 140-669; Eight Hundred 141-669; Eight Hundred 142-669</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COAST TO COAST - Continued</b>			
<b>E-Z Ride 132-380</b>			
Blade .....	7540138	3500	6950
Drive .....	7540164	2630	6863
<b>E-Z Ride 132-418; E-Z Ride 132-425; E-Z Ride 132-435</b>			
Blade .....	7540127		6966
Drive .....	7540136		6931
Variable Speed .....	7540135		6925
<b>E-Z Ride 133-380</b>			
Blade .....	7540138	3500	6950
Drive .....	7540164	2630	6863
<b>E-Z Ride 133-420</b>			
Blade .....	7540147	3520	6952
Drive .....	7540135		6925
Variable Speed .....	7540136		6931
<b>E-Z Ride 133-470; E-Z Ride 133-485</b>			
Blade .....	7540151		6967
Drive .....	7540127		6966
<b>E-Z Ride 134-380</b>			
Blade .....	7540138	3500	6950
Drive .....	7540164	2630	6863
<b>E-Z Ride 134-400</b>			
Blade .....	7540188		6951
Drive .....	7540101		6517BR
<b>E-Z Ride 134-445</b>			
Blade .....	7540178	3820	6982
Drive .....	7540185		6849
<b>Fifteen Hundred 142-960</b>			
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
<b>Fifteen Hundred 142-990</b>			
P.T.O. ....	7540165		6834
<b>HEO648</b>			
Blade .....			6854
<b>HEO648-6</b>			
Eng. To Deck .....			6854
Traction .....	13487	2370	6837
<b>HEO650</b>			
Blade .....	7540147	3520	6952
Drive .....	7540135		6925
Variable Speed .....	7540136		6931
<b>HEO655</b>			
Traction .....	4638		6830
<b>HEO660</b>			
Blade .....	7540127		6966
Drive .....	7540136		6931
Variable Speed .....	7540135		6925
<b>HEO675</b>			
Traction .....	4638		6830
<b>HEO690</b>			
Blade .....	7540218		6959
Drive .....	7540147	3520	6952
Variable Speed .....	7540136		6931
<b>Lawn Flite 134-585</b>			
Drive; W/31" Belt O.C. ....	7540136		6931
<b>Mastercraft</b>			
Eng. To Deck; W/46" Deck; W/18 H.P. ....	7540350		6464BR
<b>Sentar</b>			
Eng. To Deck; W/38" Deck; W/12.5 H.P. ....	7540329		6630BR
<b>COLUMBIA PRODUCTS</b>			
<b>132-050</b>			
Deck .....	7540246		6354
Drive .....	7540248		6431BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COLUMBIA PRODUCTS - Continued</b>			
<b>132-360</b>			
Deck .....	7540107		6830
Drive .....	7540936		6847
<b>132-390</b>			
Deck .....	7540167		6964
Drive .....	7540198		6451BR
<b>132-402; 132-412</b>		3240	
Deck .....	7540251		6809BR
Drive; W/24" Belt O.C. ....	7540187		6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>132-497</b>			
Deck .....	7540226		6551BR
Drive .....	7540145		6488BR
<b>132-498</b>			
Deck .....	7540226		6551BR
<b>132-525</b>			
Deck .....	7540195		6854
Drive .....	7540198		6451BR
<b>132-620</b>			
Belt; W/67" Belt O.C. ....	7540151		6967
Belt; W/85" Belt O.C. ....	7540266		6775BR
<b>132-730</b>		2530	
Deck; W/51" Belt O.C. ....	7540251		6809BR
Deck; W/53" Belt O.C. ....	7540250		6853
Drive .....	7540248		6431BR
<b>132-764</b>			
Deck; W/51" Belt O.C. ....	7540251		6809BR
Deck; W/53" Belt O.C. ....	7540250		6853
Drive; W/37" Belt O.C. ....	7540255		6837
Drive; W/59" Belt O.C. ....	7540245		6859
<b>132-784</b>			
Deck .....	7540246		6354
Drive; W/37" Belt O.C. ....	7540255		6837
Drive; W/59" Belt O.C. ....	7540245		6859
<b>132-796</b>			
Deck .....	7540198		6451BR
Drive .....	7540207		6842
<b>142-810</b>		2530	
Belt; W/51" Belt O.C. ....	7540251		6809BR
Belt; W/53" Belt O.C. ....	7540250		6853
<b>142-824</b>			
Deck .....	7540230		6755BR
Drive; W/40" Belt O.C. ....	7540244		6840
Drive; W/59" Belt O.C. ....	7540245		6859
Timing Belt .....	7540246		6354
<b>142-990</b>			
P.T.O. ....	7540165		6834
<b>142-995</b>			
P.T.O. ....	7540234		6841
<b>381-2</b>		3500	
Blade .....	754138		6950
<b>381-4</b>		3500	
Blade .....	754138		6950
Drive .....	754164		2630
<b>387-2; 391-2</b>		3500	
Blade .....	754138		6950
<b>391-3</b>		3500	
Blade .....	754138		6950
Drive .....	754164		2630
<b>397-2</b>		3500	
Blade .....	754138		6950
<b>401-4</b>			
Blade .....	754188		6951
Drive .....	754101		6517BR
<b>413-2</b>		3500	
Blade .....	754138		

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COLUMBIA PRODUCTS - Continued</b>			
<b>413-2 - Continued</b>			
Trans. ....	754101		6517BR
<b>421-3; 421-4</b>			
Drive .....	754136		6931
Variable Speed .....	754135		6925
<b>436-2</b>			
Blade .....			6966
Eng. To Pulley .....			6925
Pulley To Trans. ....			6931
<b>450-3; 455-3</b>		3820	
Blade .....	754178		6982
Trans. ....	754179		6950
<b>455-4</b>		3820	
Blade .....	754178		6982
Drive .....	754185		6849
<b>471-3; 477-3</b>			
Blade .....	754151		6967
Trans. ....	754127		6966
<b>485-4</b>			
Drive .....	754136		6931
<b>661-3</b>			
Blade .....	754221		6952
Deck .....	754180		6510BR
Gen. ....	7540134	7330	
Trans. ....	754182	3810	6981
<b>661-4</b>			
Blade .....	754182	3810	6981
Gen. ....	7540134	7330	
<b>667</b>		3800	
Drive .....			6980
<b>761-2</b>			
P.T.O. ....	754165		6834
<b>761-3</b>			
Blade .....	754221		6952
Deck .....	754180		6510BR
Gen. ....	7540134	7330	
Trans. ....	754182	3810	6981
<b>761-4</b>			
Blade .....	754182	3810	6981
Gen. ....	7540134	7330	
<b>961-2; 961-3; 961-4; 991-2; 991-3; 991-4</b>			
P.T.O. ....	754165		6834
<b>CONTINENTAL LAWN MOWER MFG., INC.</b>			
<b>Mark 8</b>			
Blade .....		2310	6831
<b>CO-OP</b>			
<b>3308-54</b>			
Drive .....	231362		6745
<b>4180-54</b>			
Eng. To J.S. ....	200804		6874
J.S. To Trans. ....	36770		6835
<b>COOPER</b>			
<b>Cruiser</b>			
Blade Drive .....	10876	2530	6853
Drive .....	R145		6838
Mower Drive .....	9415		6861
<b>COTTER &amp; CO.</b>			
<b>1T; 1TE; 1TEX; 1TX</b>			
Eng. To Deck .....			6854
Traction .....	13487	2370	6837
<b>2T; 2TE; 2TEX; 2TX</b>			
Eng. To Deck .....	13560		6859
Traction .....	13487	2370	6837



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COTTER &amp; CO. - Continued</b>			
<b>6-1036E4; 7-1036DE4</b>			
Blade .....	30421		6963
Trans. ....	30422		6876
<b>812</b>			
Blade .....			6854
<b>813; 814</b>			
Deck .....	17518		6960
<b>COUNTRY CLIPPER</b>			
<b>110</b>			
Blade; W/42" Deck .....			6896
Spindle; W/42" Deck .....			6983
<b>140</b>			
Drive .....			6859
<b>160</b>			
Blade; W/48" Deck .....			68107
Spindle; W/48" Deck .....			6983
<b>1800; 1810</b>			
Drive .....			6859
<b>1841KOJ-SR125</b>			
Deck Drive .....	D-3796		6901BR
Hydro. Drive .....	D-3524		6899BR
<b>1948KAJ-SR355</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3524		6899BR
<b>1948KAJ-SR1000</b>			
Deck Drive .....	D-3727		6708BR
Hydro. Drive .....	D-3769		6861BR
<b>1948KAT-SR355</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3524		6899BR
<b>1948KAT-SR1000</b>			
Deck Drive .....	D-3727		6708BR
Hydro. Drive .....	D-3769		6861BR
<b>1952KAJ-SR355; 1952KAT-SR355</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3524		6899BR
<b>2038BSJ-SR110</b>			
Deck Drive .....	D-3727		6708BR
Hydro. Drive .....	D-3754		6847BR
<b>2042BSJ-SR110</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3754		6847BR
<b>2042BSJ-SR215</b>			
Deck Drive .....	D-3727		6708BR
Hydro. Drive .....	D-3524		6899BR
<b>2048BSJ-SR215; 2048BST-SR215</b>			
Deck Drive .....	D-3775		6768BR
Hydro. Drive .....	D-3524		6899BR
<b>2048KOJ-SR1000</b>			
Deck Drive .....	D-3727		6708BR
Hydro. Drive .....	D-3769		6861BR
<b>2148KAJ-SR355</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3524		6899BR
<b>2148KAJ-SR360</b>			
Deck Drive .....	D-3775		6768BR
Hydro. Drive .....	D-3524		6899BR
<b>2148KAT-SR355</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3524		6899BR
<b>2148KAT-SR360</b>			
Deck Drive .....	D-3775		6768BR
Hydro. Drive .....	D-3524		6899BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COUNTRY CLIPPER - Continued</b>			
<b>2152KAJ-SR355; 2152KAJ-SR360;</b>			
<b>2152KAT-SR355; 2152KAT-SR360</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3524		6899BR
<b>2248BSJ-SR205; 2248BST-SR205</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3524		6899BR
<b>2248KAJ-SR365; 2248KAJ-SR375;</b>			
<b>2248KAT-SR365; 2248KAT-SR375</b>			
Deck Drive .....	D-3775		6768BR
Hydro. Drive .....	D-3524		6899BR
<b>2248KOJ-SR125</b>			
Hydro. Drive .....	D-3524		6899BR
<b>2248KOT-SR225</b>			
Deck Drive .....	D-3775		6768BR
Hydro. Drive .....	D-3524		6899BR
<b>2252BSJ-SR205; 2252KAJ-SR365;</b>			
<b>2252KAJ-SR375; 2252KAT-SR365;</b>			
<b>2252KAT-SR375</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3524		6899BR
<b>2348BVJ-SR355</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3524		6899BR
<b>2348KOJ8-SR1005</b>			
Deck Drive .....	D-3775		6768BR
Hydro. Drive .....	D-3769		6861BR
<b>2348KOJ-SR355</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3524		6899BR
<b>2348KOT8-SR1005</b>			
Deck Drive .....	D-3775		6768BR
Hydro. Drive .....	D-3769		6861BR
<b>2348KOT-SR355</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3524		6899BR
<b>2352BVJ-SR355; 2352BVT-SR355</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3524		6899BR
<b>2352KOJ8-SR1005</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2352KOJ-SR355</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3524		6899BR
<b>2352KOJ-SR1000</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3769		6861BR
<b>2352KOJ-SR1010; 2352KOJ-SR1015;</b>			
<b>2352KOT8-SR1005</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2352KOT-SR355</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3524		6899BR
<b>2352KOT-SR1000</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3769		6861BR
<b>2352KOT-SR1010; 2352KOT-SR1015</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2360KOJ-SR355</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3524		6899BR
<b>2360KOJ-SR1000</b>			
Deck Drive .....	D-3764		6898BR

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COUNTRY CLIPPER - Continued</b>			
<b>2360KOJ-SR1000 - Continued</b>			
Hydro. Drive .....	D-3769		6861BR
<b>2360KOT-SR355</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3524		6899BR
<b>2448BST-SR215</b>			
Deck Drive .....	D-3775		6768BR
Hydro. Drive .....	D-3524		6899BR
<b>2452KOJ-SR215; 2452KOT-SR215</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3524		6899BR
<b>2552KAJ8-SR1005</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2552KAJ8-SR1205</b>			
Deck Drive .....	D-3807		6688BR
Eng. To Deck .....	D-3809		6589BR
Hydro. Drive .....	D-3799		6896BR
<b>2552KAJ-SR1000</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3769		6861BR
<b>2552KAJ-SR1010</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2552KAJ-SR1200</b>			
Deck Drive .....	D-3635		6653BR
Eng. To Deck .....	D-3778		6688BR
Hydro. Drive .....	D-3777		6819BR
<b>2552KAT8-SR1005</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2552KAT8-SR1205</b>			
Deck Drive .....	D-3807		6688BR
Eng. To Deck .....	D-3809		6589BR
Hydro. Drive .....	D-3799		6896BR
<b>2552KAT-SR1000</b>			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3769		6861BR
<b>2552KAT-SR1010</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2552KAT-SR1200</b>			
Deck Drive .....	D-3635		6653BR
Eng. To Deck .....	D-3778		6688BR
Hydro. Drive .....	D-3777		6819BR
<b>2560KAJ8-SR1005</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2560KAJ-SR1000</b>			
Deck Drive .....	D-3764		6898BR
Hydro. Drive .....	D-3769		6861BR
<b>2560KAJ-SR1010; 2560KAT8-SR1005</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2560KAT-SR1000</b>			
Deck Drive .....	D-3764		6898BR
Hydro. Drive .....	D-3769		6861BR
<b>2560KAT-SR1010</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2652KALJ8-SR1205</b>			
Deck Drive .....	D-3807		6688BR
Eng. To Deck .....	D-3809		6589BR
Hydro. Drive .....	D-3799		6896BR
<b>2652KALJ-SR1200</b>			
Deck Drive .....	D-3635		6653BR
Eng. To Deck .....	D-3778		6688BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COUNTRY CLIPPER - Continued</b>			
<b>2652KALJ-SR1200 - Continued</b>			
Hydro. Drive .....	D-3777		6819BR
<b>2652KALT8-SR1205</b>			
Deck Drive .....	D-3807		6688BR
Eng. To Deck .....	D-3809		6589BR
Hydro. Drive .....	D-3799		6896BR
<b>2652KALT-SR1200</b>			
Deck Drive .....	D-3635		6653BR
Eng. To Deck .....	D-3778		6688BR
Hydro. Drive .....	D-3777		6819BR
<b>2652TKAJ-SR1015; 2652TKAT-SR1015;</b>			
<b>2660KAJ-SR1015</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2660KALJ8-SR1205</b>			
Deck Drive .....	D-3796		6901BR
Eng. To Deck .....	D-3796		6901BR
Hydro. Drive .....	D-3799		6896BR
<b>2660KALJ-SR1200</b>			
Deck Drive .....	D-3389		6900BR
Eng. To Deck .....	D-3778		6688BR
Hydro. Drive .....	D-3777		6819BR
<b>2660KALJ-SR1210; 2660KALJ-SR1210L</b>			
Deck Drive .....	D-3796		6901BR
Eng. To Deck .....	D-3809		6589BR
Hydro. Drive .....	D-3799		6896BR
<b>2660KALT8-SR1205</b>			
Deck Drive .....	D-3796		6901BR
Eng. To Deck .....	D-3796		6901BR
Hydro. Drive .....	D-3799		6896BR
<b>2660KALT-SR1200</b>			
Deck Drive .....	D-3389		6900BR
Eng. To Deck .....	D-3778		6688BR
Hydro. Drive .....	D-3777		6819BR
<b>2660KALT-SR1210</b>			
Deck Drive .....	D-3796		6901BR
Eng. To Deck .....	D-3809		6589BR
Hydro. Drive .....	D-3799		6896BR
<b>2660KAT-SR1015</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
<b>2672KALJ8-SR1205</b>			
Deck Drive .....	D-3797		6744BR
Eng. To Deck .....	D-3796		6901BR
Hydro. Drive .....	D-3799		6896BR
<b>2672KALJ-SR1200</b>			
Eng. To Deck .....	D-3778		6688BR
Hydro. Drive .....	D-3777		6819BR
<b>2672KALT8-SR1205</b>			
Deck Drive .....	D-3797		6744BR
Eng. To Deck .....	D-3796		6901BR
Hydro. Drive .....	D-3799		6896BR
<b>2672KALT-SR1200</b>			
Eng. To Deck .....	D-3778		6688BR
Hydro. Drive .....	D-3777		6819BR
<b>2748KOJ-SR225; 2748KOJ-SR360;</b>			
<b>2748KOJ-SR365</b>			
Deck Drive .....	D-3775		6768BR
Hydro. Drive .....	D-3524		6899BR
<b>2748KOJ-SR375</b>			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3524		6899BR
<b>2748KOT-SR225; 2748KOT-SR360</b>			
Deck Drive .....	D-3775		6768BR
Hydro. Drive .....	D-3524		6899BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COUNTRY CLIPPER - Continued</b>			
2752KOJL-SR360; 2752KOJL-SR365; 2752KOJL-SR375; 2752KOJ-SR225; 2752KOJ-SR360; 2752KOJ-SR365; 2752KOJ-SR375; 2752KOT-SR225; 2752KOT-SR360; 2752KOT-SR365			6902BR 6899BR
Deck Drive ..... D-3776 Hydro. Drive ..... D-3524			
<b>2752KOT-SR375</b>			6902BR 6899BR
Deck Drive ..... D-3776 Hydro. Drive ..... D-3524			
<b>2760KOJ8-SR1005</b>			6902BR 6861BR
Deck Drive ..... D-3776 Hydro. Drive ..... D-3769			
<b>2760KOJ8-SR1205</b>			6901BR 6901BR 6896BR
Deck Drive ..... D-3796 Eng. To Deck ..... D-3796 Hydro. Drive ..... D-3799			
<b>2760KOJ-SR360; 2760KOJ-SR365; 2760KOJ-SR375</b>			6902BR 6899BR
Deck Drive ..... D-3776 Hydro. Drive ..... D-3524			
<b>2760KOJ-SR1000</b>			6898BR 6861BR
Deck Drive ..... D-3764 Hydro. Drive ..... D-3769			
<b>2760KOJ-SR1010; 2760KOJ-SR1015; 2760KOJ-SR1025</b>			6902BR 6861BR
Deck Drive ..... D-3776 Hydro. Drive ..... D-3769			
<b>2760KOJ-SR1200</b>			6900BR 6688BR 6819BR
Deck Drive ..... D-3389 Eng. To Deck ..... D-3778 Hydro. Drive ..... D-3777			
<b>2760KOJ-SR1210; 2760KOJ-SR1210L; 2760KOJ-SR1220; 2760KOJ-SR1220L</b>			6901BR 6589BR 6896BR
Deck Drive ..... D-3796 Eng. To Deck ..... D-3809 Hydro. Drive ..... D-3799			
<b>2760KOT8-SR1005</b>			6902BR 6861BR
Deck Drive ..... D-3776 Hydro. Drive ..... D-3769			
<b>2760KOT-SR360; 2760KOT-SR365; 2760KOT-SR375</b>			6902BR 6899BR
Deck Drive ..... D-3776 Hydro. Drive ..... D-3524			
<b>2760KOT-SR1000</b>			6898BR 6861BR
Deck Drive ..... D-3764 Hydro. Drive ..... D-3769			
<b>2760KOT-SR1010; 2760KOT-SR1015; 2760KOT-SR1025</b>			6902BR 6861BR
Deck Drive ..... D-3776 Hydro. Drive ..... D-3769			
<b>2760KOT-SR1200</b>			6900BR 6688BR 6819BR
Deck Drive ..... D-3389 Eng. To Deck ..... D-3778 Hydro. Drive ..... D-3777			
<b>2760KOT-SR1210; 2760KOT-SR1220</b>			6901BR 6589BR 6896BR
Deck Drive ..... D-3796 Eng. To Deck ..... D-3809 Hydro. Drive ..... D-3799			
<b>2852KOJ8-SR1205; 2852KOT8-SR1205</b>			6688BR 6589BR 6896BR
Deck Drive ..... D-3807 Eng. To Deck ..... D-3809 Hydro. Drive ..... D-3799			
<b>2860KOJ8-SR1205; 2860KOT8-SR1205</b>			6901BR 6901BR 6896BR
Deck Drive ..... D-3796 Eng. To Deck ..... D-3796 Hydro. Drive ..... D-3799			

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COUNTRY CLIPPER - Continued</b>			
<b>2872KOJ8-SR1205; 2872KOT8-SR1205</b>			6744BR 6901BR 6896BR
Deck Drive ..... D-3797 Eng. To Deck ..... D-3796 Hydro. Drive ..... D-3799			
<b>3060KOJ8-SR1005</b>			6902BR 6861BR
Deck Drive ..... D-3776 Hydro. Drive ..... D-3769			
<b>3060KOJ-SR1200</b>			6900BR 6688BR 6819BR
Deck Drive ..... D-3389 Eng. To Deck ..... D-3778 Hydro. Drive ..... D-3777			
<b>3060KOT8-SR1005</b>			6902BR 6861BR
Deck Drive ..... D-3776 Hydro. Drive ..... D-3769			
<b>3060KOT-SR1200</b>			6900BR 6688BR 6819BR
Deck Drive ..... D-3389 Eng. To Deck ..... D-3778 Hydro. Drive ..... D-3777			
<b>3072KOJ-SR1200; 3072KOT-SR1200</b>			6688BR 6819BR
Eng. To Deck ..... D-3778 Hydro. Drive ..... D-3777			
<b>3160KAJ8-SR1205; 3160KAT8-SR1205</b>			6901BR 6901BR 6896BR
Deck Drive ..... D-3796 Eng. To Deck ..... D-3796 Hydro. Drive ..... D-3799			
<b>3172KAJ8-SR1205; 3172KAT8-SR1205</b>			6744BR 6901BR 6896BR
Deck Drive ..... D-3797 Eng. To Deck ..... D-3796 Hydro. Drive ..... D-3799			
<b>3560KAJ-SR1220; 3560KAJ-SR1220L; 3560KAT-SR1220</b>			6901BR 6589BR 6896BR
Deck Drive ..... D-3796 Eng. To Deck ..... D-3809 Hydro. Drive ..... D-3799			
<b>3572KAJ-SR1220; 3572KAJ-SR1220L; 3572KAT-SR1220; 3572KAT-SR1220L</b>			6744BR 6901BR 6896BR
Deck Drive ..... D-3797 Eng. To Deck ..... D-3796 Hydro. Drive ..... D-3799			
<b>3760KADJ-SR1210; 3760KADT-SR1220</b>			6901BR 6589BR 6896BR
Deck Drive ..... D-3796 Eng. To Deck ..... D-3809 Hydro. Drive ..... D-3799			
<b>3760KAJ8-SR1205</b>			6901BR 6901BR 6896BR
Deck Drive ..... D-3796 Eng. To Deck ..... D-3796 Hydro. Drive ..... D-3799			
<b>3760KAJ-SR1210</b>			6901BR 6589BR 6896BR
Deck Drive ..... D-3796 Eng. To Deck ..... D-3809 Hydro. Drive ..... D-3799			
<b>3760KAT8-SR1205</b>			6901BR 6901BR 6896BR
Deck Drive ..... D-3796 Eng. To Deck ..... D-3796 Hydro. Drive ..... D-3799			
<b>3760KAT-SR1210</b>			6901BR 6589BR 6896BR
Deck Drive ..... D-3796 Eng. To Deck ..... D-3809 Hydro. Drive ..... D-3799			
<b>3772KADJ-SR1210; 3772KADJ-SR1220; 3772KADT-SR1210; 3772KADT-SR1210L; 3772KAJ8-SR1205; 3772KAJ-SR1210; 3772KAJ-SR1210L; 3772KAT8-SR1205</b>			6744BR 6901BR 6896BR
Deck Drive ..... D-3797 Eng. To Deck ..... D-3796 Hydro. Drive ..... D-3799			
<b>15538BSJ-SR100; 15538BSJ-SR105; 18538BSJ-SR105</b>			6708BR
Deck Drive ..... D-3727			

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COUNTRY CLIPPER - Continued</b>			
15538BSJ-SR100; 15538BSJ-SR105; 18538BSJ-SR105 - Continued			
Hydro. Drive .....	D-3754		6847BR
18542BSJ-SR105			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3754		6847BR
18542BSJ-SR205			
Deck Drive .....	D-3727		6708BR
Hydro. Drive .....	D-3524		6899BR
18542BXJ-SR100			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3754		6847BR
18548BSJ-SR205			
Deck Drive .....	D-3733		6897BR
Hydro. Drive .....	D-3524		6899BR
25552KAJ-SR1025; 25552KAT-SR1025; 25552TKAJ-SR1025; 25552TKAT-SR1025; 25560KAJ-SR1025			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
25560KAJ-SR1220; 25560KAJ-SR1220L			
Deck Drive .....	D-3796		6901BR
Eng. To Deck .....	D-3809		6589BR
Hydro. Drive .....	D-3799		6896BR
25560KAT-SR1025			
Deck Drive .....	D-3776		6902BR
Hydro. Drive .....	D-3769		6861BR
25560KAT-SR1220			
Deck Drive .....	D-3796		6901BR
Eng. To Deck .....	D-3809		6589BR
Hydro. Drive .....	D-3799		6896BR
<b>Boss XL</b>			
Blade Drive; W/60" Deck .....	D-3796		6901BR
Blade Drive; W/72" Deck .....	D-3797		6744BR
Eng. To Deck; W/60" Deck .....	D-3901		6665BR
Eng. To Deck; W/72" Deck .....	D-3912		6574BR
Hydro. Drive .....	D-3900		6402BR
<b>Boulevard</b>			
Hydro. Drive .....	D-3891		6448BR
<b>Challenger</b>			
Deck Drive; W/52" Deck .....	D-3872		6860BR
Deck Drive; W/60" Deck .....	D-3914		6761BR
Hydro. Drive .....	D-3905		7099BR
<b>Charger</b>			
Deck Drive; W/52", 60" Deck .....	D-3872		6860BR
Hydro. Drive .....	D-3524		6899BR
<b>Edge XLT</b>			
Deck Drive; W/48" Deck .....	D-3775		6768BR
Deck Drive; W/52", 60" Deck .....	D-3914		6761BR
Hydro. Drive .....	D-3891		6448BR
<b>XLT</b>			
Hydro. Drive .....	D-3769		6861BR
<b>CRUSADER</b>			
<b>C340</b>			
Blade .....	7540935		6831
Transaxle .....	7540936		6847
<b>C380; C390</b>			
Blade .....	7540935		6831
Transaxle .....	7540111		6845
<b>CUB CADET</b>			
<b>44" Deck</b>			
Deck .....	7543004		6774BR
Drive .....	7543003		6614BR
<b>70; 71</b>			
Starter/Gen. ....	376230R1		3VX315

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>76</b>			
Clutch .....	549821R1		6831
Drive .....	549822R1		6868
<b>81</b>			
Drive .....	549822R1		6868
<b>87</b>			
Deck .....	7540184		6852
<b>100; 102</b>			
Starter/Gen. ....	376230R1		3VX315
<b>111</b>			
Drive .....	549822R1		6868
<b>122; 123</b>			
Starter/Gen. ....	376230R1		3VX315
<b>150</b>			
Eng. To Trans. ....	7543024		6524BR
Primary .....	1000157		6829
<b>182</b>			
Deck .....	7543006		6714BR
Drive .....	549822R1		6868
<b>234; 275</b>			
Fan & Alt .....	MD041704	7380	
<b>282</b>			
Belt; W/59" Belt O.C. ....	7543007		6859
<b>284 Diesel</b>			
Fan & Alt .....	197810984	9390	9390HD
<b>331</b>			
Blade; W/38" Deck .....	7543036		6847BR
<b>365</b>			
Deck Drive; W/44" Deck .....	754-3078		6769BR
Deck Drive; W/54" Deck .....	754-3083		6801BR
Drive .....	754-3100		6820BR
<b>382</b>			
Belt; W/86" Belt O.C. ....	7543018		6886
Belt; W/93" Belt O.C. ....	7543006		6714BR
Drive .....	549822R1		6868
<b>383</b>			
Deck .....	7543006		6714BR
Drive .....	549822R1		6868
<b>445</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540179		6950
<b>482</b>			
Deck .....	7543003		6614BR
Spindle .....	7543002		6872
Trans. ....	7543001		7072BR
<b>526</b>			
Deck .....	7540264		6639BR
Trans. - Lower; W/38" Belt O.C. ....	7540240		6511BR
Trans. - Upper; W/35" Belt O.C. ....	7540241		6494BR
<b>583</b>			
Deck .....	7543003		6614BR
Spindle .....	7543002		6872
Trans. ....	7543001		7072BR
<b>802</b>			
Deck .....	7540264		6639BR
Trans. - Lower; W/38" Belt O.C. ....	7540240		6511BR
Trans. - Upper; W/35" Belt O.C. ....	7540241		6494BR
<b>804</b>			
Deck .....	7540347		6847BR
Drive - Eng. To Trans. ....	7540290		6847
Trans. - Lower; W/38" Belt O.C. ....	7540240		6511BR
Trans. - Upper; W/35" Belt O.C. ....	7540241		6494BR
<b>805</b>			
Eng. To Deck; W/30" Deck .....	7540264		6639BR
Eng. To Deck; W/32" Deck .....	7540277		6871
Trans. ....	7543024		6524BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>830</b>			
Deck .....	7540264		6639BR
Trans. - Lower; W/38" Belt O.C. ....	7540240		6511BR
Trans. - Upper; W/35" Belt O.C. ....	7540241		6494BR
<b>1002</b>			
Belt; W/32" Deck .....	7540290		6847
Eng. To Deck .....	7540347		6847BR
Eng. To J.S. ....	7540241		6494BR
Eng. To Trans. ....	7540240		6511BR
<b>1015</b>			
Trans. ....	7543035		6890
<b>1020</b>			
Eng. To Trans. ....	7543037		6880
<b>1050</b>			
Drive; W/38" Deck .....	7543026		6860
<b>1100</b>			
Trans. ....	126496C1		6833
<b>1105</b>			
Eng. To Trans. ....	7543024		6524BR
<b>1106</b>			
Deck; 1987; W/73" Belt O.C. ....	7540344		6873
Deck; 1989-1988; W/53" Belt O.C. ....	7540348		6853
Drive - Eng. To Trans. ....	7540351		6799BR
Eng. To J.S.; W/35" Belt O.C. ....	7540241		6494BR
Eng. To J.S.; W/41" Belt O.C. ....	7540201		6841
J.S. To Trans. ....	7540240		6511BR
Trans. ....	7540241		6494BR
<b>1110</b>			
Trans. ....	7543025		6774BR
<b>1136</b>		2530	
Deck .....	7540250		6853
Trans. - Lower; W/38" Belt O.C. ....	7540240		6511BR
Trans. - Upper; W/35" Belt O.C. ....	7540241		6494BR
<b>1204</b>			
Drive; W/38" Deck .....	7543026		6860
Eng. To Deck .....	7543003		6614BR
<b>1208</b>			
Eng. To Deck .....	7540351		6799BR
Eng. To J.S. ....	7540241		6494BR
J.S. To Trans. ....	7540240		6511BR
<b>1210; 1211</b>			
Drive; W/38" Deck .....	7543026		6860
Eng. To Deck .....	7543003		6614BR
<b>1215</b>			
Eng. To Trans. ....	7543024		6524BR
<b>1220</b>			
Eng. To Trans. ....	7543037		6880
Primary .....	1000157		6829
Trans. ....	7543025		6774BR
<b>1280</b>			
Hydro. Pump .....			6933
<b>1315</b>			
Trans. ....	7543035		6890
<b>1320</b>			
Deck .....	7543036		6847BR
Eng. To Deck .....	7543038		6799BR
Eng. To Trans. ....	7543037		6880
<b>1340</b>			
Drive; W/38" Deck .....	7543026		6860
<b>1415</b>			
Deck; W/59" Belt O.C. ....	7543029		6620BR
Deck; W/63" Belt O.C. ....	7543036		6847BR
Eng. To Trans. ....	7543024		6524BR
<b>1420</b>			
Eng. To Trans. ....	7543037		6880

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>1440</b>			
Deck .....	7543050		6866
<b>1515; 1517; 1525; 1527</b>			
Drive .....	7540640		6681BR
<b>1529</b>			
Drive .....	7540640		6681BR
Mower Deck; W/46" Deck .....	7540640		6681BR
<b>1535; 1541</b>			
Drive; W/38" Deck .....	7543026		6860
<b>1572</b>			
Fan .....	7543022		6727
W.P. & Alt .....	15841-97010	7320	
<b>1605</b>			
Eng. To Trans. ....	7543024		6524BR
<b>1610</b>			
Eng. To Deck; W/44" Deck .....	7543027		6886
Trans. ....	7543025		6774BR
<b>1615</b>			
Eng. To Trans. ....	7543024		6524BR
<b>1620</b>			
Trans. ....	7543025		6774BR
<b>1641</b>			
Deck .....	7543039		6651BR
<b>1715</b>			
Eng. To Trans. ....	7543024		6524BR
<b>1720</b>			
Eng. To Trans. ....	7543037		6880
<b>1772</b>			
Fan .....	7543022		6727
W.P. & Alt .....	15841-97010	7320	
<b>1806</b>			
Drive; W/38" Deck .....	7543026		6860
Eng. To Deck .....	7543003		6614BR
<b>1810; 1811</b>			
Drive; W/38" Deck .....	7543026		6860
Drive; W/44" Deck .....	7543004		6774BR
Mower Drive; W/89" Belt O.C. ....	7543003		6614BR
<b>1812</b>			
Drive; W/38" Deck .....	7543026		6860
Eng. To Deck .....	7543003		6614BR
<b>1860; 1862</b>			
Drive; W/38" Deck .....	7543026		6860
<b>1863; 1864</b>			
P.T.O. ....	7543001		7072BR
<b>1872</b>			
Mower Drive .....	7543006		6714BR
<b>2072</b>			
Eng. To Deck .....	7543023		6994
<b>2130; 2135; 2140; 2150</b>			
Spindle .....	7543055A		6615BR
<b>AGS 2130</b>			
Deck .....	7543029		6620BR
<b>AGS 2160</b>			
Deck .....	7543039		6651BR
<b>CC 30 Rider</b>			
Deck Drive .....	954-05001		6975BR
Drive - Upper .....	954-0241A		6494BR
Lower Drive .....	954-04331		6935
<b>Cub Lo Boy 154; Cub Lo Boy 184; Cub Lo Boy 185</b>			
Fan & Gen. ....	527621R1	7480	
<b>Enforcer 44</b>			
Deck Drive .....	02000103		6558BR
P.T.O. ....	01009787		6815BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>Enforcer 44 – Continued</b>			
Trans .....	02002648		6871BR
<b>Enforcer 48</b>			
Deck Drive .....	02000154		6798BR
P.T.O. ....	01009787		6815BR
Trans .....	02002648		6871BR
<b>Enforcer 54</b>			
Deck Drive .....	02000653		6711BR
P.T.O. ....	01005011		6812BR
Trans .....	02002648		6871BR
<b>FMZ 50</b>			
Trans .....	75404189		6525BR
<b>GT1054</b>			
Deck Drive .....	95404083		6982BR
Drive .....	95404244A		6877
<b>GT1222</b>			
Deck Drive .....	75404033		6715BR
Drive .....	7540349		6637BR
<b>GT1554</b>			
Blade Drive; W/54" Deck .....	7540642		6779BR
Eng. To Trans. ....	7540349		6637BR
<b>GT2000</b>			
Deck Drive; W/42" Deck .....	954-0645A		6448BR
Deck Drive; W/50" Deck .....	954-04137A		6684BR
Deck Drive; W/54" Deck .....	954-04137A		6684BR
P.T.O. ....	954-04055		6650BR
<b>GT2042</b>			
Deck Drive .....	954-0645A		6448BR
P.T.O. ....	954-04055		6650BR
<b>GT2050</b>			
Deck Drive .....	954-04137A		6684BR
P.T.O. ....	954-04055		6650BR
<b>GT2100</b>			
Deck Drive; W/42" Deck .....	954-0645A		6448BR
Deck Drive; W/48" Deck .....	954-04045		6663BR
Deck Drive; W/50" Deck .....	954-04137A		6684BR
Deck Drive; W/54" Fabricated Deck .....	95404118		6777BR
Deck Drive; W/54" Stamped Deck .....	954-04137A		6684BR
P.T.O. ....	954-04055		6650BR
<b>GT2148</b>			
Deck Drive .....	954-04045		6663BR
P.T.O. ....	954-04055		6650BR
<b>GT2186-44</b>			
Deck Drive .....	7543039		6651BR
P.T.O. ....	75404041		6650BR
<b>GT2186-48; GT2521-48</b>			
Deck Drive .....	7543041		6810BR
P.T.O. ....	75404041		6650BR
<b>GT2523-54</b>			
Deck Drive .....	75404055		6650BR
P.T.O. ....	75404047		6684BR
<b>GT2542</b>			
Deck Drive .....	7543073		6451BR
P.T.O. ....	75404041		6650BR
<b>GT2544</b>			
Deck Drive .....	7543039		6651BR
P.T.O. ....	75404041		6650BR
<b>GT2550; GT2554</b>			
Deck Drive .....	75404047		6684BR
P.T.O. ....	75404055		6650BR
<b>GT3100; GT3200</b>			
Deck Drive; W/44" Deck .....	7543098		A106
Deck Drive; W/54" Deck .....	7540197		6604BR
P.T.O. ....	7543084		6562BR
<b>GTX1054</b>			
Deck Drive .....	95404083		6982BR
Trans .....	95404244A		6877

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>GTX2000</b>			
Deck Drive; W/42" Deck .....	954-0645A		6448BR
Deck Drive; W/50" Deck .....	954-04137A		6684BR
Deck Drive; W/54" Deck .....	954-04137A		6684BR
P.T.O. ....	954-04055		6650BR
<b>GTX2100</b>			
Deck Drive; W/42" Deck .....	954-0645A		6448BR
Deck Drive; W/48" Deck .....	954-04045		6663BR
Deck Drive; W/50" Deck .....	954-04137A		6684BR
Deck Drive; W/54" Fabricated Deck .....	95404118		6777BR
Deck Drive; W/54" Stamped Deck .....	954-04137A		6684BR
P.T.O. ....	954-04055		6650BR
<b>GTX2154; GTX2154LE</b>			
Deck Drive .....	95404118		6777BR
P.T.O. ....	954-04055		6650BR
<b>HDS 2135</b>			
Deck .....	7543029		6620BR
Primary .....	1000157		6829
<b>HDS 2185</b>			
Blade Drive; W/46" Deck .....	7543039		6651BR
Blade Drive; W/48" Deck .....	7543041		6810BR
Eng. To Deck; W/46" Deck .....	7543055A		6615BR
Eng. To Deck; W/48" Deck .....	7543068		7092BR
<b>i1046</b>			
Deck Drive .....	75404153		6777BR
Hydro. ....	75404134		6463BR
<b>i1050</b>			
Deck Drive .....	754-04077		6778BR
Hydro. ....	75404134		6463BR
<b>L48</b>			
Deck Drive .....	01005374		6810BR
P.T.O. ....	01005378		6814BR
Trans. ....	01007015		6809BR
<b>L60</b>			
Deck Drive .....	01005376		6777BR
P.T.O. ....	00068079		6816BR
Trans. ....	01007015		6809BR
<b>LGT1050</b>			
Deck Drive .....	954-04077		6778BR
Drive .....	954-04207		6879
<b>LGT1054</b>			
Deck Drive .....	954-0642		6779BR
Drive; W/Gear Drive .....	954-04297		6518BR
Drive; W/Hydro. Drive .....	954-04207		6879
<b>LGTX1050</b>			
Deck Drive .....	954-04077		6778BR
Drive .....	954-04207		6879
<b>LGTX1054</b>			
Deck Drive .....	954-0642		6779BR
Drive .....	954-04207		6879
<b>LT1018</b>			
Deck .....	7540498		6448BR
Eng. To Trans. ....	7540640		6681BR
<b>LT1022</b>			
Deck Drive .....	75404033		6715BR
Eng. To Trans. ....	7540640		6681BR
<b>LT1024</b>			
Deck Drive .....	75404048		6946BR
Eng. To Trans. ....	7540640		6681BR
<b>LT1040</b>			
Deck Drive .....	75404045		6663BR
Drive - Lower .....	7540467		6606BR
Drive - Upper .....	7540468		6556BR
<b>LT1042</b>			
Deck Drive; 2007 & Older .....	754-04060B		6776BR
Deck Drive; 2008 & Newer .....	75404045		6663BR
Drive; 2007 & Older .....	7540461		6519BR
Drive; 2008 & Newer .....	75404165		6519BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>LT1045; LT1046</b>			
Deck Drive; Ser. No. 1A257H & Before ..	75404118		6777BR
Deck Drive; Ser. No. 1A267H & After ..	75404153		6777BR
Drive; 2007 & Older ..	7540461		6519BR
Drive; 2008 & Newer ..	75404165		6519BR
<b>LT1050</b>			
Deck Drive; 2007 & Older ..	754-04077		6778BR
Deck Drive; 2008 & Newer ..	754-04164		6727BR
Drive; 2007 & Older ..	7540461		6519BR
Drive; 2008 & Newer ..	75404165		6519BR
<b>LT2042</b>			
P.T.O. ....	75404041		6650BR
Spindle .....	7543073		6451BR
<b>LT2138</b>			
P.T.O. ....	75404041		6650BR
Spindle .....	7543029		6620BR
<b>LT2180</b>			
P.T.O. ....	75404041		6650BR
Spindle .....	7543073		6451BR
<b>LTX1040</b>			
Deck Drive; 2010 & Newer ..	954-04060B		6776BR
Drive - Lower ..	7540467		6606BR
Drive - Upper ..	754-04208		7051BR
P.T.O.; 2009 & Older ..	754-0266A		6775BR
<b>LTX1042</b>			
Deck Drive; 2010 & Newer ..	954-04060B		6776BR
Drive .....	754-04207		6879
P.T.O.; 2009 & Older ..	754-0266A		6775BR
<b>LTX1042 KW</b>			
Deck Drive .....	954-04060B		6776BR
Drive; W/Hydro Gear Trans. ....	954-04207		6879
Drive; W/Tuff-Torq Trans. ....	954-04297		6518BR
<b>LTX1045; LTX1046</b>			
Deck Drive .....	75404219		6651BR
Drive .....	754-04207		6879
<b>LTX1046KW</b>			
Deck Drive .....	95404219		6651BR
Drive; W/Gear Drive .....	954-04297		6518BR
Drive; W/Hydro. Drive .....	954-04207		6879
<b>LTX1046M</b>			
Deck Drive .....	95404219		6651BR
Drive .....	954-04207		6879
<b>LTX1046VT</b>			
Deck Drive .....	75404219		6651BR
Drive .....	754-04207		6879
<b>LTX1050</b>			
Deck Drive .....	754-04240		6979BR
Drive .....	754-04207		6879
<b>LTX1050KH</b>			
Deck Drive .....	954-04240		6979BR
Drive .....	954-04207		6879
<b>LTX1050KW</b>			
Deck Drive .....	954-04240		6979BR
Drive; W/Gear Drive .....	954-04297		6518BR
Drive; W/Hydro. Drive .....	954-04207		6879
<b>LTX1050VT</b>			
Deck Drive .....	754-04240		6979BR
Drive .....	754-04207		6879
<b>M48-HN</b>			
Deck Drive .....	01005374		6810BR
P.T.O. ....	01005011		6812BR
Trans. ....	01007015		6809BR
<b>M48-KW</b>			
Deck Drive .....	01005374		6810BR
P.T.O. ....	01005011		6812BR
Trans. ....	02000068		6685BR
<b>M48-KWS</b>			
Deck Drive .....	01000399		6781BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>M48-KWS - Continued</b>			
P.T.O. ....	01005011		6812BR
Trans. ....	02000068		6685BR
<b>M50-KHS</b>			
Deck Drive .....	02000653		6711BR
P.T.O. ....	01005011		6812BR
Trans. ....	00023887		A46
<b>M54-HN</b>			
Deck Drive .....	01005375		6684BR
P.T.O. ....	01005378		6814BR
Trans. ....	01007015		6809BR
<b>M54-KH</b>			
Blade Drive .....	01005375		6684BR
P.T.O. ....	01005377		7072BR
Trans. ....	754-04212		6685BR
<b>M54-KW</b>			
Deck Drive .....	01005375		6684BR
P.T.O. ....	01005011		6812BR
Trans. ....	02000068		6685BR
<b>M60-CAT</b>			
Deck Drive .....	01005376		6777BR
P.T.O. ....	01009583		6767BR
Trans. ....	02001116		6943BR
<b>M60-KH</b>			
Deck Drive .....	01005376		6777BR
P.T.O. ....	01005377		7072BR
Trans. ....	02000068		6685BR
<b>M60-KW</b>			
Deck Drive .....	01005376		6777BR
P.T.O. ....	01005378		6814BR
Trans. ....	02000068		6685BR
<b>M60-KW LC</b>			
Deck Drive .....	01005376		6777BR
P.T.O. ....	01009583		6767BR
Trans. ....	02000408		6931BR
<b>M72-CAT</b>			
Deck Drive .....	01007937		6817BR
P.T.O. ....	02000611		6719BR
Trans. ....	02001116		6943BR
<b>M72-GN33</b>			
Deck Drive .....	01005375		6684BR
P.T.O. ....	01005378		6814BR
Trans. ....	02000068		6685BR
<b>M72-KW</b>			
Deck Drive .....	01007937		6817BR
P.T.O. ....	01007938		6949BR
Trans. ....	01007015		6809BR
<b>M72-KW LC</b>			
Deck Drive .....	01007937		6817BR
P.T.O. ....	02000611		6719BR
Trans. ....	02000408		6931BR
<b>PRO Z 148L EFI; PRO Z 148S EFI</b>			
Hydro. Drive .....	954-04317A		6448BR
<b>PRO Z 154L EFI; PRO Z 154S EFI</b>			
Deck Drive .....	954-05013		6983BR
Hydro. Drive .....	954-04317A		6448BR
<b>PRO Z 160L EFI; PRO Z 160L KW; PRO Z 160S EFI; PRO Z 160S KW</b>			
Deck Drive .....	954-05015		6769BR
Hydro. Drive .....	954-04317A		6448BR
<b>PRO Z 554L EFI; PRO Z 554L KW; PRO Z 554S KW</b>			
Deck Drive .....	954-04327		6981BR
Hydro. Drive .....	954-05037		6406BR
P.T.O. ....	954-05127		6480BR
<b>PRO Z 560L KW; PRO Z 560S KW; PRO Z 760L KW; PRO Z 760S KW</b>			
Deck Drive .....	954-04319		6845BR
Hydro. Drive .....	954-05037		6406BR

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>PRO Z 560L KW; PRO Z 560S KW; PRO Z 760L KW; PRO Z 760S KW – Continued</b>			
P.T.O. ....	954-05128		6584BR
<b>PRO Z 772L KW; PRO Z 772S KW</b>			
Deck Drive .....	954-04319		6845BR
Hydro. Drive .....	954-05037		6406BR
P.T.O. ....	954-05129		6980BR
<b>PRO Z 960L KW; PRO Z 960S KW</b>			
Deck Drive .....	954-04319		6845BR
Hydro. Drive .....	954-05037		6406BR
P.T.O. ....	954-05128		6584BR
<b>PRO Z 972L KW; PRO Z 972S KW</b>			
Deck Drive .....	954-04319		6845BR
Hydro. Drive .....	954-05037		6406BR
P.T.O. ....	954-05129		6980BR
<b>Recon 48</b>			
Deck Drive .....	01005374		6810BR
P.T.O. ....	01005378		6814BR
Trans. ....	02000068		6685BR
<b>Recon 60</b>			
Deck Drive .....	01005376		6777BR
P.T.O. ....	00068079		6816BR
Trans. ....	02000068		6685BR
<b>RZT 42</b>			
Deck Drive .....	754-04137A		6684BR
Trans. ....	75404043A	2580	
<b>RZT 50</b>			
Deck Drive .....	75404044A		6842BR
Trans. ....	75404043A	2580	
<b>RZT 50KH; RZT 50KW</b>			
Deck Drive .....	954-04044A		6842BR
Trans. ....	95404043A	2580	
<b>RZT 54</b>			
Deck Drive .....	754-04138A		6783BR
Trans. ....	75404043A	2580	
<b>RZT 54KH; RZT 54KW</b>			
Deck Drive .....	954-04138A		6783BR
Trans. ....	95404043A	2580	
<b>RZT L 34</b>			
Deck Drive .....	954-05158		7029BR
Drive .....	954-05336		6793BR
<b>RZT L 42; RZT L 42 H</b>			
Deck Drive .....	954-04033A		6715BR
Hydro. Drive .....	954-04317A		6448BR
<b>RZT L 46; RZT L 46 H</b>			
Deck Drive .....	954-04325		6977BR
Hydro. Drive .....	954-04317A		6448BR
<b>RZT L 50-KH; RZT L 50-KW</b>			
Deck Drive .....	954-05008		6873BR
Hydro. Drive .....	954-04317A		6448BR
<b>RZT L 54-KH; RZT L 54-KW</b>			
Deck Drive; 2014 & Older .....	954-04329		6767BR
Deck Drive; 2015 & Newer .....	954-04329A		6692BR
Hydro. Drive .....	954-04317A		6448BR
<b>RZT LX 46</b>			
Deck Drive .....	954-04325		6977BR
Hydro. Drive .....	954-04317A		6448BR
<b>RZT LX 50</b>			
Deck Drive .....	954-05078		7057BR
Hydro. Drive .....	954-04317A		6448BR
<b>RZT LX 54</b>			
Deck Drive .....	954-04329A		6692BR
Hydro. Drive .....	954-04317A		6448BR
<b>RZT S 42</b>			
Deck Drive .....	954-04033A		6715BR
Trans. ....	954-04317		6448BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>RZT S 46</b>			
Deck Drive .....	954-04325		6977BR
Trans. ....	954-04317		6448BR
<b>RZT S 50</b>			
Deck Drive; 2012 & Older .....	954-04330		6978BR
Deck Drive; 2013 & Newer .....	954-05008		6873BR
Trans. ....	954-04317		6448BR
<b>RZT S 54</b>			
Deck Drive; 2014 & Older .....	954-04329		6767BR
Deck Drive; 2015 & Newer .....	954-04329A		6692BR
Hydro. Drive .....	954-04317A		6448BR
<b>S 6031</b>			
Deck Drive .....	01005376		6777BR
P.T.O. ....	00068079		6816BR
<b>S 6032</b>			
Blade Drive .....	01005376		6777BR
Hydro. Drive .....	95404267		6820BR
P.T.O. ....	954-04256A		7069BR
<b>S 7232</b>			
Blade Drive .....	01007937		6817BR
Hydro. Drive .....	95404267		6820BR
P.T.O. ....	754-04255A		6598BR
<b>S 7237</b>			
Deck Drive .....	01007937		6817BR
<b>SLT1550</b>			
Deck Drive; 2007 & Older .....	754-04077		6778BR
Deck Drive; 2008 & Newer .....	754-04164		6727BR
Trans.; 2007 & Older .....	7540461		6519BR
Trans.; 2008 & Newer .....	75404165		6519BR
<b>SLT1554</b>			
Blade Drive; W/54" Deck .....	7540642		6779BR
Trans.; 2007 & Older .....	7540461		6519BR
Trans.; 2008 & Newer .....	75404165		6519BR
<b>SLTX1050</b>			
Deck Drive; 2009 & Older .....	754-04240		6979BR
Deck Drive; 2010 & Newer .....	954-04077		6778BR
Drive .....	754-04207		6879
<b>SLTX1054</b>			
Deck Drive .....	7540642		6779BR
Drive .....	754-04207		6879
<b>TANK L 48</b>			
Deck Drive .....	954-04323		6980BR
Hydro. Drive .....	954-05037		6406BR
P.T.O. ....	954-04326		6991BR
<b>TANK L 54</b>			
Deck Drive .....	954-04327		6981BR
Hydro. Drive .....	954-05037		6406BR
P.T.O. ....	954-04328		6949BR
<b>TANK L 60-KH; TANK L 60-KW</b>			
Deck Drive .....	954-04319		6845BR
Hydro. Drive .....	954-05037		6406BR
P.T.O. ....	954-04296		6721BR
<b>TANK LZ 48</b>			
Deck Drive .....	954-04323		6980BR
P.T.O. ....	954-04326		6991BR
Trans. ....	954-04320		6823BR
<b>TANK LZ 54; TANK LZ 54-KW</b>			
Deck Drive .....	954-04327		6981BR
P.T.O. ....	954-04328		6949BR
Trans. ....	954-04320		6823BR
<b>TANK LZ 60 KH; TANK LZ 60 KW</b>			
Deck Drive .....	754-04319		6845BR
P.T.O. ....	754-04296		6721BR
Trans. ....	954-04320		6823BR
<b>TANK S 60</b>			
Deck Drive .....	954-04319		6845BR
Hydro. Drive .....	954-05037		6406BR
P.T.O. ....	954-04296		6721BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>TANK SZ 48</b>			
Deck Drive .....	954-04323		6980BR
P.T.O. ....	954-04326		6991BR
Trans. ....	954-04320		6823BR
<b>TANK SZ 54</b>			
Deck Drive .....	954-04327		6981BR
P.T.O. ....	954-04328		6949BR
Trans. ....	954-04320		6823BR
<b>TANK SZ 60</b>			
Deck Drive .....	754-04319		6845BR
P.T.O. ....	754-04296		6721BR
Trans. ....	954-04320		6823BR
<b>XT1 GT50</b>			
Deck Drive .....	954-04077A		6778BR
Drive .....	954-05027A		6524BR
<b>XT1 LT42; XT1 LT42 C</b>			
Deck Drive .....	954-05021		7014BR
Drive .....	954-05027A		6524BR
<b>XT1 LT46</b>			
Deck Drive .....	954-05022A		7053BR
Drive .....	954-05027A		6524BR
<b>XT1 LT50</b>			
Deck Drive .....	954-04077A		6778BR
Drive .....	954-05027A		6524BR
<b>XT1 LT54; XT1 ST54; XT2 GX54</b>			
Deck Drive .....	954-05025A		6566BR
Drive .....	954-05027A		6524BR
<b>XT2 LX42</b>			
Deck Drive .....	954-05021		7014BR
Drive .....	954-05027A		6524BR
<b>XT2 LX46</b>			
Deck Drive .....	954-05087A		7055BR
Drive .....	954-05027A		6524BR
<b>XT2 LX50</b>			
Deck Drive .....	954-04077A		6778BR
Drive .....	954-05027A		6524BR
<b>XT2 LX54</b>			
Deck Drive .....	954-05025A		6566BR
Drive .....	954-05027A		6524BR
<b>XT3 GS</b>			
Deck Drive; W/42" Deck .....	954-0645A		6448BR
Deck Drive; W/50" Deck .....	954-04137A		6684BR
P.T.O. ....	954-04055		6650BR
<b>XT3 GSE</b>			
Deck Drive; W/42" Deck .....	954-0645A		6448BR
Deck Drive; W/48" Deck .....	954-04045		6663BR
Deck Drive; W/50" Deck .....	954-04137A		6684BR
Deck Drive; W/54" Deck .....	95404118		6777BR
P.T.O. ....	954-04055		6650BR
<b>XT3 GSX</b>			
Deck Drive; W/42" Deck .....	954-0645A		6448BR
Deck Drive; W/48" Deck .....	954-04045		6663BR
Deck Drive; W/50" Deck .....	954-04137A		6684BR
Deck Drive; W/54" Deck .....	95404118		6777BR
Deck Drive; W/60" Deck .....	954-05111		6778BR
P.T.O. ....	954-04055		6650BR
<b>Z54</b>			
Eng. ....	754-3083		6801BR
<b>Z54L</b>			
Eng.; W/165" Belt O.C. ....	754-3083		6801BR
<b>Z-Force 44</b>			
Deck Drive .....	02000103		6558BR
Hydro. ....	01008349		6755BR
P.T.O. ....	00050441		6573BR
<b>Z-Force 48</b>			
Deck Drive .....	02000154		6798BR
Hydro. ....	01008349		6755BR
P.T.O. ....	01009787		6815BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>Z-Force 50</b>			
Deck Drive .....	02000653		6711BR
Hydro. ....	01008349		6755BR
P.T.O. ....	01005011		6812BR
<b>Z-Force 54</b>			
Blade Drive .....	02000653		6711BR
P.T.O. ....	01005012		6866BR
Trans. ....	02002648		6871BR
<b>Z-Force 60</b>			
Deck Drive .....	01004752		6777BR
Hydro. ....	01008349		6755BR
P.T.O. ....	01005012		6866BR
<b>Z-Force L 48</b>			
Deck Drive .....	954-05012		6978BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force L54</b>			
Deck Drive .....	954-05013		6983BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force L60; Z-Force LE 60</b>			
Deck Drive .....	954-05015		6769BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force LX 48</b>			
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force LX 54</b>			
Deck Drive .....	954-05013		6983BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force LX 60</b>			
Deck Drive .....	954-05015		6769BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force LZ 48; Z-Force LZ 48 Commercial</b>			
Deck Drive .....	954-05012		6978BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force LZ 54</b>			
Deck Drive .....	954-05013		6983BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force LZ 60; Z-Force LZ 60 Commercial</b>			
Deck Drive .....	954-05015		6769BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force S 46</b>			
Deck Drive .....	954-04153A		6777BR
Trans. ....	95404250		6863
<b>Z-Force S 48</b>			
Deck Drive .....	954-04044A		6842BR
Trans. ....	95404250		6863
<b>Z-Force S 48 Commercial</b>			
Deck Drive .....	954-04044A		6842BR
Trans. ....	954-3092A		6943BR
<b>Z-Force S 48 LP</b>			
Deck Drive .....	954-04044A		6842BR
Trans. ....	95404250		6863
<b>Z-Force S 54</b>			
Blade Drive .....	954-04137A		6684BR
P.T.O. ....	954-04262		7072BR
Trans. ....	95404250		6863
<b>Z-Force S 60</b>			
Blade Drive .....	01005376		6777BR
P.T.O. ....	954-04262		7072BR
Trans. ....	95404250		6863
<b>Z-Force S 60 Commercial</b>			
Blade Drive .....	01005376		6777BR
P.T.O. ....	954-04262		7072BR
Trans. ....	954-3092A		6943BR
<b>Z-Force S 60 LP</b>			
Blade Drive .....	01005376		6777BR
P.T.O. ....	954-04262		7072BR
Trans. ....	95404250		6863

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>Z-Force SX 48 KW</b>			
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force SX 54 KW</b>			
Deck Drive .....	954-05013		6983BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force SX 60 KW</b>			
Deck Drive .....	954-05015		6769BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force SZ 48; Z-Force SZ 48 Commercial</b>			
Deck Drive .....	954-05012		6978BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force SZ 54</b>			
Deck Drive .....	954-05013		6983BR
Hydro. Drive .....	954-04317A		6448BR
<b>Z-Force SZ 60; Z-Force SZ 60 Commercial</b>			
Deck Drive .....	954-05015		6769BR
Hydro. Drive .....	954-04317A		6448BR
<b>ZTT42</b>			
Hydro. ....	75404134		6463BR
P.T.O. ....	75404185		6709BR
<b>ZTT46</b>			
Deck Drive .....	75404153		6777BR
Hydro. ....	75404134		6463BR
<b>ZTT50</b>			
Deck Drive .....	754-04077		6778BR
Hydro. ....	75404134		6463BR
<b>Z-Wing 48</b>			
Deck Drive .....	02000154		6798BR
<b>CUSHMAN</b>			
<b>222</b>			
Eng. To Trans.; W/2-Cyl. Eng. ....	622725	2285	
<b>DAVIS</b>			
<b>856; 857; 858</b>			
Eng. To Blade .....	13560		6859
Traction .....	13487	2370	
<b>DEINES</b>			
<b>212-40</b>			
Drive .....	300254		6862
Trans. ....	100157		6837
<b>1140</b>			
Blade .....	400810		B100
Drive; W/11, 13 H.P. Eng. ....	400898		6860
Hydro.; W/60" Belt O.C.; 1987 & Older ...	400898		6860
Hydro.; W/62" Belt O.C. ....	300254		6862
<b>1240</b>			
Drive .....	300137		6865
Trans. ....	100157		6837
<b>1440</b>			
Deck .....	400180		6898
Drive .....	300137		6865
Trans. ....	100157		6837
<b>1640T</b>			
Drive .....	400248		6864
Trans. ....	100293		6839
<b>1648</b>			
Blade .....			6898
Drive .....	400182		6868
Trans. ....	100157		6837
<b>1648T</b>			
Blade .....			6898
Drive .....	400288		6866
Trans. ....	100293		6839
<b>1660</b>			
Blade .....	400181		A136
Drive .....	300137		6865

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DEINES - Continued</b>			
<b>1660 - Continued</b>			
Trans. ....	100157		6837
<b>D148</b>			
Blade .....	400122		6894
Drive .....	300137		6865
Trans. ....	100157		6837
<b>D160</b>			
Blade .....	300255		A128
Drive .....	300254		6862
Trans. ....	100157		6837
<b>D1840T</b>			
Drive .....	400248		6864
Trans. ....	100293		6839
<b>D1848T</b>			
Blade .....			6898
Drive .....	400288		6866
Trans. ....	100293		6839
<b>D1850T</b>			
Deck; W/102" Belt O.C. ....			A100
Deck; W/139" Belt O.C. ....			B136
Eng. To Gear Box .....			6867
Trans. ....			6840
<b>D1860T</b>			
Blade .....	400181		A136
Drive .....	300254		6862
Trans. ....	100293		6839
<b>DVC8</b>			
Vacuum Attachment .....	200235		6821
<b>DVC11</b>			
Vacuum Attachment .....	400123		6840
<b>DVC40</b>			
Vacuum Attachment .....	400650		6831
<b>DVC50</b>			
Vacuum Attachment .....	200519		6835
<b>Magnum 1800</b>			
Hydro. ....	100293		6839
<b>Magnum 2000</b>			
Belt; W/60" Deck .....	400945		6868
Belt; W/72" Deck .....	400923		6876
Blade .....	400288		6866
Hydro. ....	100293		6839
<b>Marty D-1440-3</b>			
Traction; W/34" Belt O.C. ....			6834
<b>Marty J</b>			
Trans. ....	100293		6839
<b>DILLE &amp; MCGUIRE</b>			
<b>2842</b>			
Trans. ....	100293		6839
<b>2843; 2844; 2855</b>			
Belt; W/25" Belt O.C. ....	8672B		6825
Belt; W/31" Belt O.C. ....	9407B		6831
<b>A02260; KKTR424A; KKTR426A; KKTR426AE</b>			
Blade .....	BE103	3280	
Trans. ....	BE104	3580	6958
<b>R324</b>			
Trans. ....	BE104	3580	6958
<b>R414; R424</b>			
Belt; W/25" Belt O.C. ....	8672B		6825
Belt; W/31" Belt O.C. ....	9407B		6831
<b>R525</b>			
Belt; W/25" Belt O.C. ....	8672B		6825
Belt; W/29" Belt O.C. ....	8671B		6829
<b>TJ426</b>			
Belt; W/29" Belt O.C. ....	8671B		6829



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DILLE &amp; MCGUIRE - Continued</b>			
<b>TR321</b>			
Lower Drive .....	BE106	1210	6721
Upper Drive .....	BE105	3460	6946
<b>TR324; TR324A</b>			
Lower Drive .....	BE107	1260	6726
Upper Drive .....	BE108	3430	6943
<b>TR424; TR424A; TR426A; TR426AE; TR426BD; TR426BE; TR426C</b>			
Blade .....	BE103	3280	
Trans. ....	BE104	3580	6958
<b>TRA321; TRB321</b>			
Lower Drive .....	BE106	1210	6721
Upper Drive .....	BE105	3460	6946
<b>DIXIE CHOPPER</b>			
<b>3066LP</b>			
Deck Drive .....	2006B144R		6787BR
Eng. To Deck; 2011 & Newer .....	2010B98W		6480BR
Eng. To Trans.; 2010 & Older .....	2006B42R		6677BR
Eng. To Trans.; 2011 & Newer .....	2010B42W		6677BR
<b>3074LP</b>			
Deck Drive .....	2006B162R		6853BR
Eng. To Deck; 2010 & Older .....	2006B99W		6857BR
Eng. To Deck; 2011 & Newer .....	2010B99W		6857BR
<b>3566D</b>			
Deck Drive .....	2006B144R		6787BR
Eng. To J.S. ....	2006B41R		6852BR
<b>3574D</b>			
Deck Drive .....	2006B162R		6853BR
<b>3666D</b>			
Deck Drive .....	2006B144R		6787BR
Eng. To J.S.; 2010 & Older .....	2006B41R		6852BR
<b>3674D</b>			
Deck Drive .....	2006B162R		6853BR
<b>5018</b>			
Blade .....	30202		6979
Deck .....	30203		6584BR
Trans. ....	20256		6514BR
<b>Blackhawk 2248; Blackhawk 2454</b>			
Drive .....	4354028		7091BR
<b>Blackhawk 2460</b>			
Deck Drive .....	4350706		6770BR
Drive .....	4354028		7091BR
<b>Blackhawk HP 2248; Blackhawk HP 2454</b>			
Drive .....	4354028		7091BR
<b>Blackhawk HP 2460</b>			
Deck Drive .....	4350706		6770BR
Drive .....	4354028		7091BR
<b>Blackhawk HP 2548; Blackhawk HP 2554</b>			
Drive .....	4354028		7091BR
<b>Blackhawk HP 2560</b>			
Deck Drive .....	4350706		6770BR
Drive .....	4354028		7091BR
<b>Classic 2550; Classic 2750; Classic 2750HP</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck; 2010 & Older .....	2006B85W		6839BR
Eng. To Deck; 2011 & Newer .....	2010B85W		6839BR
Eng. To Trans.; 2010 & Older .....	2006B41R		6852BR
Eng. To Trans.; 2011 & Newer .....	2010B42W		6677BR
<b>Classic 2750KW</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck .....	2010B85W		6839BR
<b>Classic 2750T</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck .....	2010B99W		6857BR
<b>Classic 2750W</b>			
Deck Drive .....	2006B112R		6665BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DIXIE CHOPPER - Continued</b>			
<b>Classic 2750W - Continued</b>			
Eng. To Deck .....	2010B99W		6857BR
Eng. To Trans. ....	2006B63R		6855BR
<b>Classic 2760</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Deck; 2010 & Older .....	2008B87W		6649BR
Eng. To Deck; 2011 & Newer .....	2010B87W		6649BR
Eng. To Trans.; 2010 & Older .....	2006B41R		6852BR
Eng. To Trans.; 2011 & Newer .....	2010B42W		6677BR
<b>Classic 2760KW</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Deck .....	2010B88W		7072BR
<b>Classic 2760T</b>			
Deck Drive .....	2006B128R		6946BR
<b>Classic 2760W</b>			
Deck Drive .....	2006B128R		6946BR
Eng. To Trans. ....	2006B63R		6855BR
<b>Classic 2960EFI</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Trans. ....	2010B42W		6677BR
<b>Classic 3060HP</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Deck; 2010 & Older .....	2008B87W		6649BR
Eng. To Deck; 2011 & Newer .....	2010B87W		6649BR
Eng. To Trans.; 2010 & Older .....	2006B41R		6852BR
Eng. To Trans.; 2011 & Newer .....	2010B42W		6677BR
<b>Classic 3160EFI; Classic 3160HP; Classic 3160KOE; Classic 3160KW</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Deck .....	2010B88W		7072BR
<b>Classic 3360HP</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Deck; 2010 & Older .....	2008B87W		6649BR
Eng. To Deck; 2011 & Newer .....	2010B87W		6649BR
Eng. To Trans.; 2010 & Older .....	2006B41R		6852BR
Eng. To Trans.; 2011 & Newer .....	2010B42W		6677BR
<b>Classic 3360W</b>			
Deck Drive .....	2006B128R		6946BR
Eng. To Trans. ....	2006B63R		6855BR
<b>Classic 3372HP</b>			
Deck Drive .....	2006B160R		6741BR
Eng. To Trans.; 2010 & Older .....	2006B41R		6852BR
Eng. To Trans.; 2011 & Newer .....	2010B42W		6677BR
<b>Classic 3472EFI</b>			
Deck Drive .....	2006B160R		6741BR
<b>Classic 3560T</b>			
Deck Drive .....	2006B128R		6946BR
<b>Classic 3572HP; Classic 3572KOE; Classic 3572KW; Classic 3672BR</b>			
Deck Drive .....	2006B160R		6741BR
<b>CNG66</b>			
Deck Drive .....	2006B144R		6787BR
Eng. To Trans. ....	2006B42R		6677BR
<b>Deck</b>			
Deck; W/42" Deck .....	63203		6582BR
Deck; W/50" Deck .....	30203		6584BR
<b>Deck Spindle</b>			
Belt; W/42" Deck .....			6891
Belt; W/50" Deck .....			B103
Belt; W/60" Deck .....			B128
Belt; W/72" Deck .....			B162
<b>Eco-Eagle</b>			
Deck Drive .....	2006B144R		6787BR
Eng. To Deck .....	2010B99W		6857BR
Eng. To Trans. ....	2010B42W		6677BR
<b>Engine-Deck</b>			
Eng. To Deck; W/42" Deck .....	B80		6983
Eng. To Deck; W/50" Deck .....	30204		6515BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DIXIE CHOPPER - Continued</b>			
<b>Engine-Deck - Continued</b>			
Eng. To Deck; W/60" Deck .....	65080		6676BR 6984
Eng. To Deck; W/72" Deck .....			
<b>Engine-Transmission</b>			
Eng. To Trans. ....	63204		6677BR
<b>Flatlander</b>			
Eng. To Deck; W/60" Deck .....	65080		6676BR
<b>Iron Eagle 2044; Iron Eagle 2344</b>			
Deck Drive .....	2008B101R		6994BR
Eng. To Deck .....	2008B100W		6904BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Iron Eagle 2350; Iron Eagle 2550</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck .....	2008B97W		6416BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Iron Eagle 2560</b>			
Deck Drive .....	2006B128R		6946BR
Eng. To Deck .....	2008B100W		6904BR
Eng. To Trans. ....	2006A62R		6943BR
<b>LP3000-60</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Deck .....	2006B88W		7072BR
Eng. To Trans. ....	2006B42R		6677BR
<b>LP3000-72</b>			
Deck Drive .....	2006B160R		6741BR
Eng. To Deck .....	2006B88W		7072BR
Eng. To Trans. ....	2006B42R		6677BR
<b>LT2700-60D</b>			
Eng. To Deck; W/60" Deck .....	9907B130		6646BR
<b>LX2001-42</b>			
Deck Drive .....	63203		6582BR
Eng. To Deck .....	68081		6754BR
Eng. To Trans. ....	9907B41		6852BR
<b>Magnum 2244; Magnum 2244R</b>			
Deck Drive .....	2008B101R		6994BR
Eng. To Deck .....	2010B100W		6904BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Magnum 2250; Magnum 2250HP; Magnum 2250R; Magnum 2350EFI</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck .....	2010B97W		6416BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Magnum 2460; Magnum 2460HP; Magnum 2460R</b>			
Deck Drive .....	2006B128R		6946BR
Eng. To Deck .....	2010B100W		6904BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Magnum 2550BR; Magnum 2550KO</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck .....	2010B97W		6416BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Magnum 2560BR; Magnum 2560KO</b>			
Deck Drive .....	2006B128R		6946BR
Eng. To Deck .....	2010B100W		6904BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Magnum 2750</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck; 2010 & Older .....	2008B97W		6416BR
Eng. To Deck; 2011 & Newer .....	2010B97W		6416BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Magnum 2760</b>			
Deck Drive .....	2006B128R		6946BR
Eng. To Deck; 2010 & Older .....	2008B100W		6904BR
Eng. To Deck; 2011 & Newer .....	2010B100W		6904BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Magnum HP 2244HP</b>			
Deck Drive .....	2008B101R		6994BR
Eng. To Deck .....	2010B100W		6904BR
Eng. To Trans. ....	2006A62R		6943BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DIXIE CHOPPER - Continued</b>			
<b>Magnum HP 2250HP</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck .....	2010B97W		6416BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Magnum HP 2460HP</b>			
Deck Drive .....	2006B128R		6946BR
Eng. To Deck .....	2010B100W		6904BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Magnum HP 2750EFI</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck .....	2010B97W		6416BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Magnum HP 2760EFI</b>			
Deck Drive .....	2006B128R		6946BR
Eng. To Deck .....	2010B100W		6904BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Silver Eagle 2550</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck; 2010 & Older .....	2006B81W		6866BR
Eng. To Deck; 2011 & Newer .....	2010B81W		6866BR
Eng. To Trans. ....	2006B64R		6502BR
<b>Silver Eagle 2550KW</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck .....	2010B81W		6866BR
Eng. To Trans. ....	2006B64R		6502BR
<b>Silver Eagle 2660EFI</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Deck .....	2010B85W		6839BR
Eng. To Trans. ....	2006B64R		6502BR
<b>Silver Eagle 2734</b>			
Deck Drive .....	2006B80R		6812BR
Eng. To Deck .....	2010B92W		6991BR
<b>Silver Eagle 2744</b>			
Deck Drive .....	2006B94R		6575BR
Eng. To Deck; 2011 & Newer .....	2010B92W		6991BR
<b>Silver Eagle 2750</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck; 2010 & Older .....	2006B81W		6866BR
Eng. To Deck; 2011 & Newer .....	2010B81W		6866BR
Eng. To Trans. ....	2006B64R		6502BR
<b>Silver Eagle 2750EFI</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck .....	2010B81W		6866BR
Eng. To Trans. ....	2006B64R		6502BR
<b>Silver Eagle 2760EFI</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Deck .....	2010B85W		6839BR
Eng. To Trans. ....	2006B64R		6502BR
<b>Silver Eagle 2760HP</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Deck; 2010 & Older .....	2006B85W		6839BR
Eng. To Deck; 2011 & Newer .....	2010B85W		6839BR
Eng. To Trans. ....	2006B64R		6502BR
<b>Silver Eagle 2760KW</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Deck .....	2010B85W		6839BR
Eng. To Trans. ....	2006B64R		6502BR
<b>Silver Eagle 2772EFI; Silver Eagle 2772KW</b>			
Deck Drive .....	2006B160R		6741BR
Eng. To Deck .....	2010B92W		6991BR
Eng. To Trans. ....	2006B64R		6502BR
<b>Silver Eagle 2960EFI</b>			
Deck Drive .....	2006B130R		6646BR
Eng. To Deck .....	2010B85W		6839BR
Eng. To Trans. ....	2006B64R		6502BR
<b>SP2800-60 EFI</b>			
Eng. To Deck; W/60" Deck .....	9907B130		6646BR
<b>Stryker 2548</b>			
Deck Drive .....	301160		6817BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DIXIE CHOPPER - Continued</b>			
<b>Stryker 2548 – Continued</b>			
Trans. ....	200704		6887BR
<b>Stryker 2554</b>			
Deck Drive .....	301253		6982BR
Trans. ....	200704		6887BR
<b>Stryker 2648</b>			
Deck Drive .....	301160		6817BR
Trans. ....	200704		6887BR
<b>Stryker 2654</b>			
Deck Drive .....	301253		6982BR
Trans. ....	200704		6887BR
<b>X1701-50</b>			
Deck Drive .....	9907B112		6665BR
Eng. To Trans. ....	9907B41		6852BR
<b>X2001-60; X2503-60</b>			
Eng. To Deck; W/60" Deck .....	9907B130		6646BR
<b>Xcaliber 3160KW</b>			
Deck Drive .....	2006B128R		6946BR
Eng. To Deck .....	2010B94W		6575BR
<b>Xcaliber 3356</b>			
Deck Drive .....	2008B120R		6589BR
Eng. To Deck; 2011 & Newer .....	2010B92W		6991BR
Eng. To Trans.; 2010 & Older .....	2006B42R		6677BR
Eng. To Trans.; 2011 & Newer .....	2010B42W		6677BR
<b>Xcaliber 3360EFI; Xcaliber 3360KOE</b>			
Deck Drive .....	2006B128R		6946BR
Eng. To Deck .....	2010B94W		6575BR
<b>Xcaliber 3366</b>			
Deck Drive .....	2006B144R		6787BR
Eng. To Deck; 2011 & Newer .....	2010B98W		6480BR
Eng. To Trans.; 2010 & Older .....	2006B42R		6677BR
Eng. To Trans.; 2011 & Newer .....	2010B42W		6677BR
<b>Xcaliber 3366EFI</b>			
Deck Drive .....	2006B144R		6787BR
Eng. To Deck .....	2010B97W		6416BR
<b>Xcaliber 3374</b>			
Deck Drive .....	2006B162R		6853BR
Eng. To Deck; 2010 & Older .....	2006B99W		6857BR
Eng. To Deck; 2011 & Newer .....	2010B99W		6857BR
<b>Xcaliber 3566KW</b>			
Deck Drive .....	2006B144R		6787BR
Eng. To Deck .....	2010B97W		6416BR
<b>Xcaliber 3574EFI; Xcaliber 3574KOE; Xcaliber 3574KW; Xcaliber 3674BR</b>			
Deck Drive .....	2006B162R		6853BR
Eng. To Deck .....	2010B98W		6480BR
Eng. To Trans. ....	2013B42R		6677BR
<b>Xcaliber 4074</b>			
Deck Drive .....	2006B162R		6853BR
Eng. To Deck; 2010 & Older .....	2006B99W		6857BR
Eng. To Deck; 2011 & Newer .....	2010B99W		6857BR
<b>Xcaliber Twin 5474</b>			
Deck Drive .....	2006B162R		6853BR
Eng. To Deck .....	2010B99W		6857BR
<b>XF2500-60</b>			
Deck Drive .....	9907B130		6646BR
Eng. To Deck .....	9907B85		6753BR
Eng. To Trans. ....	9907B41		6852BR
<b>XF2600-60 EFI; XG2703-60; XK2503-60; XT3000-60; XT3200-60; XW2000-60; XW2002-60; XW2300-60; XW2400-60; XW2500-60</b>			
Eng. To Deck; W/60" Deck .....	9907B130		6646BR
<b>XW2503-60; XWD2600-60; XWF2700-60; XWK2303-60; XWK2501-60</b>			
Eng. To Deck; W/60" Deck .....	9907B130		6646BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DIXIE CHOPPER - Continued</b>			
<b>XXW4000-72</b>			
Clutch .....	20256		6514BR
Deck Drive .....	68162		6853BR
Eng. To Deck .....	68082		6702BR
<b>Zee 2 – 2142; Zee 2 – 2342KO; Zee 2 – 2348; Zee 2 – 2348BR; Zee 2 – 2348HP; Zee 2 – 2348KO</b>			
Traction .....	200572		6889BR
<b>Zee 2 – 2354; Zee 2 – 2354BR; Zee 2 – 2354HP; Zee 2 – 2354KO</b>			
Deck Drive .....	300997		7058BR
Traction .....	200572		6889BR
<b>Zee 3 – 2344</b>			
Deck Drive .....	2008B101R		6994BR
Eng. To Deck .....	2010B100W		6904BR
Eng. To Trans. ....	2006A62R		6943BR
<b>Zee 3 – 2650</b>			
Deck Drive .....	2006B112R		6665BR
Eng. To Deck .....	2010B97W		6416BR
Eng. To Trans. ....	2006A62R		6943BR
<b>DIXON</b>			
<b>Black Bear 34</b>			
Deck Drive .....	539117811		6858BR
Hydro. Drive .....	539118012		6896BR
<b>Black Bear 44</b>			
Deck Drive .....	539118156		6759BR
Hydro. Drive .....	539118012		6896BR
<b>D20KH42</b>			
Deck Drive .....	532429636		6653BR
Drive .....	532130969		6757BR
<b>D21KH46</b>			
Deck Drive .....	532405143		6821BR
Drive .....	532130969		6757BR
<b>D22KH46</b>			
Deck Drive .....	532405143		6821BR
Hydro. Drive .....	532130969		6757BR
<b>D24KH54</b>			
Deck Drive .....	532196103		6767BR
Drive; 2012 & Older .....	532125907		6713BR
Drive; 2013 & Newer .....	532140294		6434BR
<b>D25KH48</b>			
Deck Drive .....	532197242		6786BR
Hydro. Drive .....	532130969		6757BR
<b>D26KH48</b>			
Deck Drive .....	532197242		6786BR
Drive .....	532130969		6757BR
<b>D26KH54</b>			
Deck Drive .....	532196103		6767BR
Hydro. Drive .....	532125907		6713BR
<b>D2246YT</b>			
Deck Drive .....	532405143		6821BR
Drive .....	532130969		6757BR
<b>D2548YT</b>			
Deck Drive .....	532197242		6786BR
Drive .....	532130969		6757BR
<b>D2654GT</b>			
Deck Drive .....	532196103		6767BR
Drive .....	532125907		6713BR
<b>DX148; DX152; DX161</b>			
Hydro. Drive .....	574870901		7007BR
<b>DX254</b>			
Deck Drive; 2012 & Older .....	574285901		6878BR
Deck Drive; 2013 & Newer .....	575658401		7034BR
Hydro. Drive .....	575586701		7066BR
<b>DX260</b>			
Deck Drive; 2012 & Older .....	522829601		6879BR
Deck Drive; 2013 & Newer .....	575658403		6938BR

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DIXON - Continued</b>			
<b>DX260 – Continued</b>			
Hydro. Drive .....	575586701		7066BR
<b>DX260D</b>			
Deck Drive .....	522860201	6935BR	
Hydro. Drive .....	574890001	6930BR	
<b>DX272</b>			
Deck Drive; 2012 & Older .....	574286001	6882BR	
Deck Drive; 2013 & Newer .....	575658405	7002BR	
Hydro. Drive .....	575586701	7066BR	
<b>Grizzly 52</b>			
Deck Drive .....	539114550	6598BR	
Hydro. Drive .....	539104334	6756BR	
<b>Grizzly 60; Grizzly 72</b>			
Hydro. Drive .....	539104334	6756BR	
<b>Grizzly SE 60</b>			
Deck Drive .....	522829601	6879BR	
Hydro. Drive .....	573978301	6675BR	
<b>Grizzly SE 72</b>			
Deck Drive .....	574286001	6882BR	
Hydro. Drive .....	573978301	6675BR	
<b>Kodiak 52</b>			
Deck Drive .....	539114557	6597BR	
<b>Kodiak SE 52</b>			
Deck Drive .....	522811301	6692BR	
<b>Kodiak SE 61</b>			
Deck Drive .....	522811401	6853BR	
<b>Ram 44 Mag</b>			
Hydro. Drive .....	539104334	6756BR	
<b>Ram 48</b>			
Deck Drive; 2009 & Older .....	539109243	6785BR	
Deck Drive; 2010 .....	539103013	6778BR	
Hydro. Drive .....	539120772	6793BR	
<b>Ram 48 ZT</b>			
Deck Drive .....	539103013	6778BR	
Hydro. Drive .....	539120772	6793BR	
<b>Ram 50</b>			
Hydro. Drive; W/Kawasaki Eng.; W/B. & S. Eng. ....	539101957	6425BR	
Hydro. Drive; W/Kohler Eng. ....	539120772	6793BR	
<b>Ram 50 Mag</b>			
Hydro. Drive .....	539104334	6756BR	
<b>Ram 52</b>			
Deck Drive .....	539107709	6783BR	
Hydro. Drive .....	539120772	6793BR	
<b>Ram 61</b>			
Hydro. Drive .....	539101957	6425BR	
<b>Ram Ultra 50</b>			
Deck Drive .....	539132000	6569BR	
Hydro. Drive .....	539111445	6553BR	
<b>Ram Ultra 60</b>			
Deck Drive .....	539132001	6860BR	
Hydro. Drive .....	539111445	6553BR	
<b>Ram Ultra 61</b>			
Deck Drive .....	539132002	6747BR	
Hydro. Drive .....	539111445	6553BR	
<b>Ram Ultra 72</b>			
Deck Drive .....	539132003	6881BR	
Hydro. Drive .....	539111445	6553BR	
<b>SpeedZTR 30</b>			
Deck Drive .....	574173002	68100	
Hydro. Drive .....	539120806	7026BR	
<b>SpeedZTR 36</b>			
Deck Drive .....	539117811	6858BR	
Hydro. Drive .....	539120772	6793BR	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DIXON - Continued</b>			
<b>SpeedZTR 42</b>			
Deck Drive; 2010 .....	539117245		6589BR
Hydro. Drive; 2009 & Older .....	539120772		6793BR
Hydro. Drive; 2010 .....	539110411		6755BR
<b>SpeedZTR 42 SE</b>			
Deck Drive .....	539117245		6589BR
Hydro. Drive .....	539110411		6755BR
<b>SpeedZTR 44</b>			
Deck Drive .....	539118156		6759BR
Hydro. Drive .....	539120772		6793BR
<b>SpeedZTR 46</b>			
Deck Drive .....	539117245		6589BR
Hydro. Drive .....	539110411		6755BR
<b>SpeedZTR 48 SE</b>			
Deck Drive .....	539109243		6785BR
Hydro. Drive .....	539110411		6755BR
<b>SpeedZTR 54</b>			
Deck Drive .....	539114557		6597BR
Hydro. Drive .....	539110411		6755BR
<b>Ultra 52</b>			
Deck Drive; 2010 & Older .....	539114557		6597BR
Deck Drive; 2011 & Newer .....	522811301		6692BR
Hydro. Drive .....	574870901		7007BR
<b>Ultra 52 SE</b>			
Deck Drive .....	522811301		6692BR
Hydro. Drive .....	574870901		7007BR
<b>Ultra 61</b>			
Deck Drive .....	539104335		6760BR
Hydro. Drive .....	574870901		7007BR
<b>ZTR 300</b>			
Traction .....	2426	3440	6944
<b>ZTR 301; ZTR 302; ZTR 304; ZTR 308; ZTR 311; ZTR 312</b>			
Deck .....	2412		6974
Trans. ....	2426	3440	
<b>ZTR 361</b>			
Mower Drive .....			69100
Traction .....	2469		A44
<b>ZTR 421; ZTR 422</b>			
Blade .....	6111		6840BR
Deck .....	6109		6434BR
<b>ZTR 424</b>			
Drive .....	6109		6434BR
Mower Drive .....	6111		6840BR
<b>ZTR 425</b>			
Blade .....	6361		6649BR
Deck .....	6360		6986
Traction .....	2469		A44
<b>ZTR 426; ZTR 427; ZTR 428; ZTR 429</b>			
Drive .....	6109		6434BR
Mower Drive .....	6111		6840BR
<b>ZTR 501</b>			
Aux. Blower .....	4812		6866
Deck .....	6111		6840BR
Drive .....	9236		6993
Traction .....	1714		6639BR
<b>ZTR 502</b>			
Aux. Blower .....	4812		6866
Mower Drive .....	6111		6840BR
<b>ZTR 503</b>			
Deck .....	6111		6840BR
Hydro. ....	1765		6827
Traction .....	1714		6639BR
<b>ZTR 542 HG</b>			
Deck .....	6111		6840BR
<b>ZTR 3014</b>			
Blade .....	6109		6434BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DIXON - Continued</b>			
<b>ZTR 3014 - Continued</b>			
P.T.O. To Deck .....	7725		6972
P.T.O. To Pump .....	7650		6841
<b>ZTR 3303</b>			
Drive .....	7650		6841
P.T.O. To Blade .....	7725		6972
<b>ZTR 3304</b>			
Deck .....	7725		6972
P.T.O. ....	7650		6841
<b>ZTR 3362</b>			
Drive .....	7650		6841
<b>ZTR 4421</b>			
Blade .....	6109		6434BR
<b>ZTR 4422</b>			
Blade .....	6109		6434BR
Deck .....	6111		6840BR
<b>ZTR 4423; ZTR 4424</b>			
Blade .....	6109		6434BR
P.T.O. To Deck .....	7725		6972
P.T.O. To Pump .....	2497		6844
<b>ZTR 5020</b>			
Blade .....			6939
P.T.O. To Deck .....			6938
P.T.O. To Pump .....	1714		6639BR
Pump .....	1765		6827
<b>ZTR 5022</b>			
Blade .....	6109		6434BR
P.T.O. To Deck .....	7725		6972
P.T.O. To Pump .....	2497		6844
<b>ZTR 5422 HG</b>			
Deck .....	6109		6434BR
Eng. To P.T.O. ....	1714		6639BR
P.T.O. To Deck .....	6111		6840BR
P.T.O. To Pump .....	1765		6827
<b>ZTR 5502 HG</b>			
Blade .....			69100
Eng. To P.T.O. ....	1714		6639BR
P.T.O. To Deck .....	6111		6840BR
Pump .....	1765		6827
<b>ZTR 5601 HG</b>			
Deck .....			6939
Eng. To P.T.O. ....	1714		6639BR
P.T.O. To Deck .....			6938
P.T.O. To Pump .....	1765		6827
<b>ZTR 6601 HG</b>			
Pump .....	1765		6827
<b>DYNAMARK</b>			
<b>16/40</b>			
Deck .....	48044		6454BR
<b>44-1900; 44-1901</b>			
Blade; W/63" Belt O.C. ....	45186	2630	6863
Blade; W/71" Belt O.C. ....	47390		6871
Trans. ....			6856
<b>44-1902; 44-1903; 44-1923; 44-2006</b>			
Blade .....	48044		6454BR
Trans. ....	39454		6463BR
<b>141 AMF Tractor</b>			
P.T.O. ....	1501245		6887
Tiller Attachment .....	1501105		6951
<b>1010</b>			
P.T.O.; W/10 H.P. Eng. ....	514132M1		6830
<b>1136</b>			
Blade .....			6971
Trans. ....	39454		6463BR
<b>1142</b>			
Eng. To Deck; W/42" Deck .....	49330		6379

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
<b>1234-00</b>			
Blade .....	20368	2290	6829
<b>1236-00; 1237-00; 1237-01; 1237-02; 1238-00; 1238-02</b>			
Blade .....	20368	2290	6829
Trans. ....	23164		6825
<b>1245-00; 1247-00; 1247-02</b>			
Blade .....	20368	2290	6829
<b>1260-00</b>			
Blade .....	45187	2440	6844
Trans. ....			6856
<b>1261-00; 1261-01; 1261-02</b>			
Blade .....	45186	2630	6863
Trans. ....			6856
<b>1261-03</b>			
Blade .....	47390		6871
Trans. ....			6856
<b>1261-20</b>			
Blade .....	26659	3720	6972
<b>1262-00; 1262-01; 1262-02</b>			
Blade .....	29281	3780	6978
<b>1263-00; 1263-01</b>			
Blade .....	36607	3630	6963
<b>1265-00</b>			
Blade .....	30839	3730	6973
<b>1267-00; 1267-01; 1268-00; 1268-01; 1268-02</b>			
Blade .....	26659	3720	6972
<b>1269-00; 1269-01</b>			
Blade .....	45187	2440	6844
Trans. ....			6856
<b>1270-00; 1270-01</b>			
Blade .....	31053	2270	6827
Trans. ....	30997		6847
<b>1272-00; 1272-01; 1272-02</b>			
Blade .....	31053	2270	6827
Trans. ....	30998		6842
<b>1274-00</b>			
Blade .....			6971
Trans. ....	39454		6463BR
<b>1277-00</b>			
Blade .....	41505		6835
Trans. ....	30998		6842
<b>1278-00; 1278-01; 1278-02</b>			
Blade .....	31053	2270	6827
Trans. ....	30998		6842
<b>1280-00; 1281-00; 1281-03</b>			
Blade .....	39456	3690	6969
Trans. ....	39454		6463BR
<b>1281-07; 1281-08; 1281-09</b>			
Blade .....	42111		6630BR
Trans.; W/63" Belt O.C. ....	39455		6863
Trans.; W/88" Belt O.C. ....	39454		6463BR
<b>1281-11; 1281-12; 1281-13; 1281-15; 1281-17</b>			
Blade .....			6971
Trans. ....	39454		6463BR
<b>1282-00; 1282-03; 1282-04</b>			
Blade .....	39456	3690	6969
Trans. ....	39454		6463BR
<b>1282-06; 1282-07</b>			
Blade .....		3710	6971
Trans. ....	39454		6463BR
<b>1282-10</b>			
Blade .....	42111		6630BR
Trans.; W/63" Belt O.C. ....	39455		6863
Trans.; W/88" Belt O.C. ....	39454		6463BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
<b>1283-00</b>		<b>3690</b>	<b>6969</b>
Blade .....	39456		<b>6463BR</b>
Trans. ....	39454		
<b>1283-01; 1283-02</b>			
Blade .....	42111		<b>6630BR</b>
Trans.; W/63" Belt O.C. ....	39455		<b>6863</b>
Trans.; W/88" Belt O.C. ....	39454		<b>6463BR</b>
<b>1284-00</b>			
Blade .....	46466		<b>6983</b>
Trans. ....	39454		<b>6463BR</b>
<b>1284-02</b>			
Blade .....	48044		<b>6454BR</b>
Trans. ....	39454		<b>6463BR</b>
<b>1284-05</b>			
Blade .....	46466		<b>6983</b>
Trans. ....	39454		<b>6463BR</b>
<b>1284-06</b>			
Blade .....	48044		<b>6454BR</b>
Trans. ....	39454		<b>6463BR</b>
<b>1288-00</b>			
Blade .....			<b>6898</b>
Deck .....	44313		<b>6852</b>
Trans. ....	39454		<b>6463BR</b>
<b>1288-01; 1288-02; 1288-0300</b>			
Blade .....			<b>6898</b>
Deck .....			<b>6853</b>
Trans. ....	39454		<b>6463BR</b>
<b>1290-00; 1290-01; 1290-02; 1290-05; 1290-50;</b>			
<b>1290-51; 1291-00; 1291-01; 1291-02; 1291-50</b>			
Blade .....	42846		<b>6850</b>
Trans. ....	42858	<b>2390</b>	
<b>1291-51</b>			
Blade .....	42846		<b>6850</b>
Trans. ....	42858	<b>2390</b>	
<b>1292-00</b>			
Blade .....	42881	<b>3710</b>	<b>6971</b>
Trans. ....	42858	<b>2390</b>	
<b>1292-10</b>			
Blade .....	42846		<b>6850</b>
<b>1292-50; 1293-00; 1293-50</b>			
Blade .....	42881	<b>3710</b>	<b>6971</b>
Trans. ....	42858	<b>2390</b>	
<b>1294-00; 1294-01; 1294-02</b>			
Blade .....	45186	<b>2630</b>	<b>6863</b>
Trans. ....			<b>6841</b>
<b>1295-00; 1295-07</b>			
Blade .....	47611		<b>6463BR</b>
Trans.; W/32" Belt O.C. ....	44190		<b>6832</b>
Trans.; W/41" Belt O.C. ....			<b>6841</b>
<b>1422-00</b>			
Deck .....	511277M2		<b>6850</b>
<b>2235-00; 2236-00</b>			
Blade .....	20368	<b>2290</b>	<b>6829</b>
Trans. ....	23164		<b>6825</b>
<b>2608</b>			
Trans.; W/26", 32", 36" Deck .....			<b>6856</b>
<b>3180-00; 3180-01; 3181-00; 3181-03; 3182-01</b>			
Blade .....			<b>6971</b>
Mower Drive .....	49330		<b>6379</b>
Trans. ....			<b>6888</b>
Transaxle .....			<b>6888</b>
<b>3184-00</b>			
Blade .....			<b>6971</b>
Trans. ....			<b>6856</b>
<b>3188-08</b>			
Blade .....			<b>6971</b>
Trans. ....	39454		<b>6463BR</b>

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
<b>3188-09</b>			
Blade .....			<b>6971</b>
Trans. ....	50737		<b>6884</b>
<b>3188-10</b>			
Blade .....			<b>6971</b>
Trans. ....	39454		<b>6463BR</b>
<b>3188-12; 3188-15; 3188-16; 3188-18</b>			
Blade .....			<b>6971</b>
Trans. ....	50737		<b>6884</b>
<b>3188-20</b>			
Mower Drive .....			<b>6971</b>
Transaxle .....	54758		<b>6551BR</b>
<b>3189-00; 3189-02; 3189-03; 3189-05; 3189-06</b>			
Blade .....	45186	<b>2630</b>	<b>6863</b>
Trans. ....			<b>6856</b>
<b>3189-09</b>			
Mower Drive .....	45186		<b>6863</b>
Trans. ....			<b>6856</b>
<b>3208-04; 3208-05</b>			
Eng. To Deck .....	45186		<b>6863</b>
<b>3294-00; 3294-01</b>			
Blade .....	47611		<b>6463BR</b>
Trans. ....	51855		<b>6841</b>
<b>3294-02</b>			
Mower Drive .....	47390		<b>6871</b>
Trans. ....	51855		<b>6841</b>
<b>3504-02; 3504-04</b>			
Blade .....	47390		<b>6871</b>
Trans. ....			<b>6856</b>
<b>3510-03; 3526-00</b>			
Trans. ....	39454		<b>6463BR</b>
<b>3606-05</b>			
Trans. ....			<b>6856</b>
<b>3610; 3611</b>			
Blade .....			<b>6971</b>
<b>3611-1200</b>			
Blade .....			<b>6971</b>
Trans. ....	50737		<b>6884</b>
<b>3612</b>			
Blade .....			<b>6971</b>
<b>4211; 4212; 4214</b>			
Eng. To Deck; W/42" Deck .....	49330		<b>6379</b>
<b>4218</b>			
Eng. To Deck; W/42" Deck .....	49330		<b>6379</b>
Trans. ....			<b>6889</b>
<b>4222; 4224; 4225; 4226</b>			
Trans. ....			<b>6889</b>
<b>4518-12</b>			
Eng. To Deck .....	49878		<b>6467BR</b>
<b>5167-00</b>			
Blade .....	45187	<b>2440</b>	<b>6856</b>
Trans. ....			
<b>5180-00; 5180-01; 5180-04; 5180-07; 5180-08</b>			
Blade .....	49330		<b>6379</b>
Trans. ....			<b>6888</b>
<b>5180-26</b>			
Blade .....	48044		<b>6454BR</b>
Trans. ....	39454		<b>6463BR</b>
<b>5181-00; 5181-01; 5181-05; 5181-06</b>			
Blade .....	49330		<b>6379</b>
Trans. ....			<b>6888</b>
<b>5181-14</b>			
Trans. ....			<b>6888</b>
<b>5182-00</b>			
Blade .....	49330		<b>6379</b>



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>				<b>DYNAMARK - Continued</b>			
<b>5182-00 - Continued</b>				<b>5239-00; 5239-40; 5239-42; 5240-00; 5240-02; 5240-30; 5240-32</b>			
Eng. To Deck .....	49330		6379	Trans. ....	20368	2290	
Trans. ....			6888	<b>5244-30; 5244-32; 5244-34</b>			
<b>5182-04</b>				Blade .....	20368	2290	6829
Trans. ....			6888	Trans. ....	23164		6825
<b>5184-00; 5184-01</b>				<b>5246-00; 5246-01; 5246-30; 5246-31; 5246-32; 5246-34</b>			
Trans. ....			6856	Blade .....	26659	3720	6972
<b>5184-04</b>				<b>5252-00</b>			
Blade .....	49330		6379	Blade .....	47611		6463BR
Trans. ....			6888	Trans. ....			6841
<b>5184-05; 5184-06; 5184-07; 5184-08; 5184-09; 5184-10</b>				<b>5267</b>			
Trans. ....			6856	Trans.; W/26", 32", 36" Deck .....			6856
<b>5184-0701; 5184-0990</b>				<b>5267-00; 5267-01; 5267-03; 5267-05; 5267-06; 5267-08; 5267-09; 5267-10</b>			
Eng. To Deck .....	49878		6467BR	Blade .....	47390		6871
<b>5188-13; 5188-14; 5188-15; 5188-17; 5188-25; 5188-29</b>				Trans. ....			6856
Blade .....	49330		6379	<b>5267-14</b>			
Trans. ....	39454		6463BR	Blade .....	45186	2630	6863
<b>5188-34</b>				Trans. ....			6856
Blade .....	49330		6379	<b>5267-15</b>			
Trans. ....	52467		6887	Blade .....	45187	2440	6844
<b>5188-36; 5188-37</b>				Trans. ....			6856
Trans. ....	50737		6884	<b>5267-21</b>			
<b>5188-38</b>				Blade .....	45186	2630	6863
Blade .....			6971	Trans. ....			6856
Primary .....	50597		6830	<b>5267-90; 5267-91</b>			
Trans. ....	50737		6884	Blade .....	45187	2440	6844
<b>5188-47; 5188-49; 5188-50; 5188-51</b>				Trans. ....			6856
Primary .....	50597		6830	<b>5268</b>			
Trans. ....	50737		6884	Trans.; W/26", 32", 36" Deck .....			6856
<b>5188-60</b>				<b>5268-00; 5268-01; 5268-02; 5268-04</b>			
Blade .....			6971	Blade .....		2630	6863
Transaxle .....	54758		6551BR	Trans. ....			6856
<b>5188-63</b>				<b>5268-05</b>			
Blade .....			6971	Blade .....	45187	2440	6844
<b>5188-80</b>				Trans. ....			6856
Transaxle .....	54758		6551BR	<b>5268-06; 5268-07; 5268-08; 5268-09; 5268-11; 5268-12</b>			
<b>5188-81</b>				Blade .....	45186	2630	6863
Blade .....			6971	Trans. ....			6856
<b>5188-83</b>				<b>5270-02; 5270-03; 5270-35; 5270-38</b>			
Blade .....			6971	Blade .....	31053		6827
Transaxle .....	54758		6551BR	Trans. ....	30997		6847
<b>5188-90</b>				<b>5271-00; 5271-01; 5271-02; 5271-03; 5271-33; 5271-35; 5271-39; 5271-41; 5271-42; 5271-43</b>			
Blade .....	49330		6379	Blade .....	31053	2270	6827
Trans. ....	52467		6887	Trans. ....	30998		6842
<b>5188-2500; 5188-2501</b>				<b>5271-46; 5271-47; 5271-48; 5271-49; 5274-00; 5274-01; 5275-00</b>			
Deck .....	49878		6467BR	Blade .....	31053	2270	6827
Trans. ....	50737		6884	Trans. ....	30998		6842
<b>5188-2600</b>				<b>5276-00; 5276-02</b>			
Deck; W/82" Belt O.C. ....	48044		6454BR	Blade .....	41505		6835
Deck; W/84" Belt O.C. ....	49878		6467BR	Trans. ....	30998		6842
Trans. ....	50737		6884	<b>5276-03</b>			
<b>5188-2601; 5188-2700; 5188-2701; 5188-2702; 5188-3000; 5188-3001; 5188-3002; 5188-3100; 5188-3103</b>				Blade .....	41505	2340	6834
Deck .....	49878		6467BR	Trans. ....	30998		6842
Trans. ....	50737		6884	<b>5276-04; 5276-05; 5276-06; 5276-08</b>			
<b>5236-00; 5236-01; 5236-02; 5236-03; 5236-04; 5236-06; 5236-32</b>				Blade .....		2340	6834
Trans. ....	20368	2290		Trans. ....	30998		6842
<b>5238-00; 5238-02; 5238-30; 5238-32; 5238-40</b>				<b>5277-00</b>			
Blade .....	20368	2290	6829	Blade .....	41505		6835
Trans. ....	23164		6825	Trans. ....	30998		6842

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
<b>5277-01; 5277-02</b>			
Blade .....		2340	6834
Trans. .... 30998			6842
<b>5278-01</b>			
Blade .....	31053	2270	6827
Trans. .... 30998			6842
<b>5280-01</b>			
Trans. ....			6856
<b>5281-00; 5281-01; 5281-02</b>			
Blade .....	39456	3690	6969
Trans. .... 39454			6463BR
<b>5281-03</b>			
Blade .....	42111		6630BR
Trans. .... 39455			6863
<b>5281-10; 5282-00; 5282-01; 5282-02; 5282-03</b>			
Blade .....	39456	3690	6969
Trans. .... 39454			6463BR
<b>5282-04</b>			
Blade .....	42111		6630BR
Trans. .... 39454			6463BR
<b>5282-05</b>			
Blade .....	39456	3690	6969
Trans. .... 39454			6463BR
<b>5282-06; 5282-07</b>			
Blade .....	42111		6630BR
Trans. .... 39454			6463BR
<b>5282-08; 5282-09</b>			
Blade .....		3710	6971
Trans. .... 39454			6463BR
<b>5282-10; 5282-11</b>			
Blade .....	39456	3690	6969
Trans. .... 39454			6463BR
<b>5282-12; 5282-14</b>			
Blade .....	42111		6630BR
Trans. .... 39454			6463BR
<b>5282-16; 5282-18</b>			
Blade .....		3710	6971
Trans. .... 39454			6463BR
<b>5282-22; 5282-23; 5282-25</b>			
Blade; W/71" Belt O.C. ....		3710	6971
Blade; W/82" Belt O.C. ....	48044		6454BR
Trans. .... 39454			6463BR
<b>5283-00; 5283-01; 5283-02</b>			
Blade .....	39456	3690	6969
Trans. .... 39454			6463BR
<b>5283-03; 5283-05</b>			
Blade .....	42111		6630BR
Trans. .... 39455			6863
<b>5285-04; 5285-06; 5285-07; 5285-08; 5285-09</b>			
Blade .....	42111		6630BR
Trans. .... 39454			6463BR
<b>5285-10; 5285-11</b>			
Blade .....	39456	3690	6969
Trans. .... 39454			6463BR
<b>5285-12</b>			
Blade; W/69" Belt O.C. ....	39456	3690	6969
Blade; W/70" Belt O.C. ....	42111		6630BR
Trans. .... 39454			6463BR
<b>5285-13</b>			
Blade .....	39456	3690	6969
Trans. .... 39454			6463BR
<b>5285-14</b>			
Blade; W/69" Belt O.C. ....	39456	3690	6969
Blade; W/70" Belt O.C. ....	42111		6630BR
Trans. .... 39454			6463BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
<b>5285-15; 5285-16; 5285-17; 5285-20; 5285-22;</b>			
<b>5285-23; 5285-25; 5285-26; 5285-27; 5285-28</b>			
Blade .....	48044		6454BR
Trans. .... 39454			6463BR
<b>5285-29; 5285-30; 5285-32; 5285-33; 5285-34;</b>			
<b>5285-36; 5285-39; 5285-40; 5285-41; 5285-42</b>			
Blade .....	48044		6454BR
Trans. .... 39454			6463BR
<b>5285-44; 5285-46; 5285-47; 5285-48; 5285-49;</b>			
<b>5285-50; 5285-51; 5285-52; 5285-53; 5285-54</b>			
Blade .....	48044		6454BR
Trans. .... 39454			6463BR
<b>5285-56; 5285-58; 5285-59; 5285-62</b>			
Blade .....	48044		6454BR
Trans. .... 39454			6463BR
<b>5286</b>			
Gear Box .....	511277M3		6850
P.T.O. Drive .....	514132M1		6830
<b>5288-00; 5288-02; 5288-03; 5288-05; 5288-06</b>			
Blade .....		3710	6971
Trans. .... 39454			6463BR
<b>5288-07</b>			
Blade .....	46466		6983
Trans. .... 39454			6463BR
<b>5288-08</b>			
Blade .....		3710	6971
Trans. .... 39454			6463BR
<b>5288-10; 5288-11</b>			
Blade .....	46466		6983
Trans. .... 39454			6463BR
<b>5288-12; 5288-13; 5288-14; 5288-15</b>			
Blade .....	48044		6454BR
Trans. .... 39454			6463BR
<b>5288-16</b>			
Blade .....		3710	6971
Trans. .... 39454			6463BR
<b>5288-17; 5288-18; 5288-19; 5288-20</b>			
Blade .....	48044		6454BR
Trans. .... 39454			6463BR
<b>5288-21</b>			
Blade .....		3710	6971
Trans. .... 39454			6463BR
<b>5288-23; 5288-24; 5288-26; 5288-30; 5288-33;</b>			
<b>5288-34; 5288-35; 5288-36</b>			
Blade .....	48044		6454BR
Trans. .... 39454			6463BR
<b>5288-37</b>			
Blade .....		3710	6971
Trans. .... 39454			6463BR
<b>5288-38; 5288-47; 5288-51; 5288-52</b>			
Blade .....	48044		6454BR
Trans. .... 39454			6463BR
<b>5288-55</b>			
Blade .....	48044		6454BR
Trans. .... 52467			6887
<b>5288-56</b>			
Belt .....	52467		6887
<b>5288-57</b>			
Blade .....	49330		6379
Primary .....	50597		6830
<b>5288-91</b>			
Blade .....	48044		6454BR
Trans. .... 39454			6463BR
<b>5288-5200</b>			
Blade .....	49330		6379
Trans. .... 39454			6463BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
5289 Trans.; W/26", 32", 36" Deck .....			6856
5289-00 Blade .....		2630	6863
Trans. ....			6856
5289-02 Blade .....	45186	2630	6863
Trans. ....			6856
5289-03 Blade .....		2630	6863
Trans. ....			6856
5289-04; 5289-05; 5289-07; 5289-08; 5289-12; 5289-14; 5289-15 Blade .....	45186	2630	6863
Trans. ....			6856
5289-16; 5289-17; 5289-19; 5289-21; 5289-23; 5289-25; 5289-26; 5289-28; 5289-30; 5289-31 Blade .....	47390		6871
Trans. ....			6856
5289-32; 5289-40; 5289-41; 5289-42; 5289-43 Blade .....	47390		6871
Trans. ....			6856
5289-46 Blade .....	47390		6871
Trans.; W/39" Belt O.C. ....	42858	2390	
Trans.; W/56" Belt O.C. ....			6856
5289-51 Blade .....	47390		6871
Trans. ....			6856
5289-55 Mower Drive .....	45186		6863
Trans. ....			6856
5290-00; 5290-10; 5290-11; 5290-12; 5290-13; 5290-20 Blade .....	42846		6850
Trans. ....	42858	2390	
5291-00; 5292-00 Blade .....			6971
Trans. ....	42858	2390	
5292-10 Blade .....	42846		6850
Trans. ....	42858	2390	
5293-00; 5293-10; 5293-20 Blade; W/50" Belt O.C. ....	42846		6850
Blade; W/71" Belt O.C. ....	42881	3710	6971
Trans. ....	42858	2390	
5294-02; 5294-03; 5294-04; 5294-06 Blade .....	45186	2630	6863
Trans. ....			6841
5294-09; 5294-17; 5294-18; 5294-19; 5294-20 Blade .....	47611		6463BR
Trans. ....			6841
5294-21; 5294-22 Blade .....	51855		6841
Mower Drive .....	47390		6871
5296-00; 5296-02; 5296-03; 5296-04 Blade .....			6971
Trans. ....	39454		6463BR
5296-07; 5296-08 Blade .....	46466		6983
Trans. ....	39454		6463BR
5296-09; 5296-10 Blade .....	48044		6454BR
Trans. ....	39454		6463BR
5297-00; 5297-01; 5297-02; 5297-05 Trans. ....	39454		6463BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
5297-06; 5297-07; 5297-10; 5297-11; 5297-12; 5297-13 Blade .....			6898
Deck .....			6853
Trans. ....	39454		6463BR
5380-00 P.T.O. ....	25807		6933
Primary .....	25812	2190	
Secondary .....	24551	2295	
5381-31 Blade .....			6898
Deck .....			6853
5404 Mower Attachment; W/102" Belt O.C. ....	511275M1		A100
5482-01 Blade .....	39456	3690	6969
50336 Blade .....	29798		6827
50337-3 Blade .....	31053		6827
Trans. ....	30997		6847
81330; 81360 Blade .....	42111		6630BR
Trans. ....	39454		6463BR
503347-1; 503347-3; 503349-1; 503349-4 Blade .....	31053	2270	6827
Trans. ....	30998		6842
503370-1; 503370-3; 503371 Blade .....	31053		6827
Trans. ....	30997		6847
4518010 Deck .....			6978
12660000; 12660100; 12660300; 12660400; 12660500; 12660600; 12660700; 12660800; 12660900; 12661000 Blade .....	26659	3720	6972
12661100; 12661200; 12661300; 12670000; 12670100; 12680000; 12680100; 12680200 Blade .....	26659	3720	6972
12930100 Blade .....	42881	3710	6971
Trans. ....	42858	2390	
52883100 Trans. ....	39454		6463BR
A3611-000 Deck .....	58170		6675BR
A3812-010 Deck .....	300680		6408BR
Drive .....	54758		6551BR
A3912-000 Deck .....	300680		6408BR
Drive .....	57214		6775BR
A3912-010; A3912-20; A4012-020 Trans. ....			6850
A4016-000 Deck .....	48044		6454BR
LM2-2451A Blade .....	41405		6835
Trans. ....	30998		6842
LM2-2551A Blade .....	39456	3690	
Trans. ....	39454		6463BR
LM2-2551B Blade .....	42111		6630BR
Trans. ....	39454		6463BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
<b>LM2-2621A</b>		3690	
Blade .....	39456		
Trans. ....	39454		6463BR
<b>LM2-2621B</b>			6630BR
Blade .....	42111		6463BR
Trans. ....	39454		
<b>LM2-2622A</b>			6971
Blade .....			6463BR
Trans. ....	39454		
<b>LM2-2633A</b>			6898
Blade .....			6852
Deck .....	44313		6463BR
Trans. ....	39454		
<b>LM60</b>			6463BR
Trans. ....	39454		
<b>RP24A</b>		2260	6826
Blade .....	RP8096	2240	6824
Eng. ....		2270	6827
Trans. ....	RP8095		
<b>RR140; RR140A; RR140C</b>		2270	6827
Trans. ....	RP8095		
<b>TD170; TD170A</b>		2200	6820
Belt .....	LP2154		
<b>Turfmaster 526</b>		2440	
Belt .....	45187		
<b>EDKO</b>			
<b>5 H.P. Walking</b>		3460	6946
Forward .....	21416	1150	
Reverse .....	21415		
<b>Power Wheel</b>		3620	6962
Drive .....	20939		B59
Trans. ....	27055		
<b>ENCORE</b>			
<b>34K15Z; 34K350Z</b>			6573BR
Blade .....	363210		6985BR
Pump .....	583385		
<b>42B350Z; 42K17Z; 42K450Z</b>			6548BR
Pump .....	423272		
<b>48B20X</b>			6768BR
Deck Drive .....	483053		6548BR
Pump .....	423272		
<b>48B450Z</b>			6768BR
Deck Drive .....	483053		6548BR
Pump .....	423272		
<b>48K19X; 48K19Z; 48K550Z</b>			6768BR
Deck Drive .....	483053		6548BR
Pump .....	423272		
<b>52B25X; 52B550Z; 52K21Z</b>			6661BR
Deck Drive .....	523472		6548BR
Pump .....	423272		
<b>52K23A</b>			6989BR
Clutch .....	823267		6992BR
Deck .....	823243		6985BR
Pump .....	583385		
<b>52K23X</b>			6661BR
Deck Drive .....	523472		6548BR
Pump .....	423272		
<b>52K25A</b>			6989BR
Clutch .....	823267		6992BR
Deck .....	823243		6985BR
Pump .....	583385		
<b>52K26X</b>			6661BR
Deck Drive .....	523472		6548BR
Pump .....	423272		

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ENCORE - Continued</b>			
<b>52K27L</b>			6990BR
Clutch .....	583517		6992BR
Deck .....	823243		6985BR
Pump .....	583385		
<b>52K550R</b>			B116
Blade .....	523108		A58
Pump; W/O Lift Kit .....	523106		
<b>52K555G</b>			B116
Blade .....	523108		6514BR
Clutch; W/Lift Kit .....	523374		A58
Pump; W/O Lift Kit .....	523106		
<b>52K650Z</b>			6661BR
Deck Drive .....	523472		6548BR
Pump .....	423272		
<b>52K650ZP</b>			6514BR
Clutch .....	523374		6992BR
Deck .....	823243		6985BR
Pump .....	583385		
<b>52K700ZP</b>			6989BR
Clutch .....	823267		6992BR
Deck .....	823243		6985BR
Pump .....	583385		
<b>52K850ZP</b>			6990BR
Clutch .....	583517		6992BR
Deck .....	823243		6985BR
Pump .....	583385		
<b>60B25X; 60K25X</b>			6722BR
Deck Drive .....	603068		6548BR
Pump .....	423272		
<b>60K25Z</b>			6722BR
Deck Drive .....	603068		6548BR
Pump .....	423272		
<b>60K26X</b>			6722BR
Deck Drive .....	603068		6548BR
Pump .....	423272		
<b>61B27LD</b>			6514BR
Clutch .....	523374		6787BR
Deck .....	823242		6985BR
Pump .....	583385		
<b>61B31LP</b>			6514BR
Clutch .....	523374		6787BR
Deck .....	823242		
<b>61K25A</b>			6989BR
Clutch .....	823267		6787BR
Deck .....	823242		6985BR
Pump .....	583385		
<b>61K27L</b>			6990BR
Clutch .....	583517		6787BR
Deck .....	823242		6985BR
Pump .....	583385		
<b>61K28A3</b>			6989BR
Clutch .....	823267		6787BR
Deck Drive .....	823242		6985BR
Pump .....	583385		
<b>61K550R</b>			A58
Pump; W/O Lift Kit .....	523106		
<b>61K555G</b>			6514BR
Clutch; W/Lift Kit .....	523374		A58
Pump; W/O Lift Kit .....	523106		
<b>72B27LD</b>			6514BR
Clutch .....	523374		6769BR
Deck .....	583153		6985BR
Pump .....	583385		
<b>72B31LP</b>			6514BR
Clutch .....	523374		6769BR
Deck .....	583153		
<b>72K27L</b>			6990BR
Clutch .....	583517		





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ENCORE - Continued</b>			
<b>72K27L - Continued</b>			
Deck	583153		6769BR
Pump	583385		6985BR
<b>72K28A3</b>			
Clutch	583517		6990BR
Deck Drive	583153		6769BR
Pump	583385		6985BR
<b>72K850ZP</b>			
Clutch; W/Kawasaki Eng.	583517		6990BR
Deck Drive	583153		6769BR
<b>B850PFC</b>			
Blade Drive; W/52" Deck	823243		6992BR
Blade Drive; W/61" Deck	823242		6787BR
Blade Drive; W/72" Deck	583153		6769BR
P.T.O.	583517		6990BR
Pump	583385		6985BR
<b>EC52FX730V3</b>			
Deck Drive	543097		6878BR
<b>EC52FX730V5</b>			
Deck Drive	543097		6878BR
Hydro. Drive	543005		7046BR
<b>EC60FX730V3</b>			
Deck Drive	543103		6880BR
<b>EC60FX801V5</b>			
Deck Drive	543103		6880BR
Hydro. Drive	543005		7046BR
<b>ED34FS600V</b>			
Deck Drive	353111		6715BR
Pump Drive	353112		6986BR
<b>ER48FX730V</b>			
Pump	453311		7005BR
<b>ER52FX730V</b>			
Eng. To Deck	453214		6865BR
Pump	453311		7005BR
<b>F34B18; F34B24; F34K15; F34K20</b>			
Deck Drive	353111		6715BR
Pump	353112		6986BR
<b>F42B18; F42B24; F42K17; F42K20</b>			
Deck Drive	353114		6987BR
Pump	353112		6986BR
<b>F48B18; F48B24; F48K19; F48K20</b>			
Deck Drive	353139		6988BR
Pump	353112		6986BR
<b>K850PFC</b>			
Blade Drive; W/52" Deck	823243		6992BR
Blade Drive; W/61" Deck	823242		6787BR
Blade Drive; W/72" Deck	583153		6769BR
P.T.O.	583517		6990BR
Pump	583385		6985BR
<b>Prowler Front Cut</b>			
Clutch	823267		6989BR
Deck; W/52" Deck	823243		6992BR
Deck; W/61" Deck	823242		6787BR
P.T.O.; W/Kawasaki Eng.	523374		6514BR

**ENGINEERING PRODUCTS**

<b>42" Deck</b>			
Eng. To Hitch; 1980	810070		6870
Eng. To Hitch; 1998-1981	810074		6874
Hitch To Header; 1980			6867
Hitch To Header; 1998-1981	810070		6870
Traction; 1998-1980	810064		6864
<b>48" Deck</b>			
Belt; 1976-1971	810094		6894
Belt; 1977	810064		6864
Belt; 1998-1978	810048		6848
Belt; Jim Dandy; 1979-1974	810080		6880
Belt; Power King; 1979-1974; W/24"			
Wheels	810092		6892

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ENGINEERING PRODUCTS - Continued</b>			
<b>48" Deck - Continued</b>			
Belt; W/Parallel Hitch; 1998-1980; W/85" Belt O.C.	810085		6886
Belt; W/Parallel Hitch; 1998-1980; W/87" Belt O.C.	810087		6887
Belt; W/Std. Hitch; 1998-1980; W/80" Belt O.C.	810080		6880
Belt; W/Std. Hitch; 1998-1980; W/85" Belt O.C.	810085		6886
Belt; W/Std. Hitch; W/87" Belt O.C.	810087		6887
Belt; W/Std. Hitch; W/89" Belt O.C.	810089		6889
Drive	810036		6836
<b>1200 Series</b>			
Belt; W/29" Belt O.C.	810029		6829
Belt; W/89" Belt O.C.	810089		6889
<b>Jim Dandy</b>			
Belt; 1979-1974	810070		6870
Belt; 1998-1974	810048		6848
Belt; Ser. No. 21299 & Before			6831
Belt; Ser. No. 21300 & After	810025		6825
Belt; W/60" Deck; 1979-1974	810080		6880
Belt; W/60" Deck; 1998-1980; W/87" Belt O.C.	810087		6887
Belt; W/60" Deck; 1998-1980; W/91" Belt O.C.	810089		6889
Belt; W/Std. Hitch; 1998-1980; W/89" Belt O.C.; W/60" Deck	810089		6889
Belt; W/Std. Hitch; 1998-1980; W/92" Belt O.C.; W/60" Deck	810092		6892
<b>Power King</b>			
Belt; 1974; W/72" Belt O.C.	810072		6872
Belt; 1974; W/94" Belt O.C.	810094		6894
Belt; 1998-1974; W/52" Belt O.C.	810052		6852
Belt; W/60" Deck; 1979-1974; W/16" Wheels	810085		6886
Belt; W/60" Deck; 1979-1974; W/24" Wheels	810092		6892
Belt; W/60" Deck; 1998-1980; W/87" Belt O.C.	810087		6887
Belt; W/60" Deck; 1998-1980; W/91" Belt O.C.	810089		6889
Belt; W/Std. Hitch; 1998-1980; W/89" Belt O.C.; W/60" Deck	810089		6889
Belt; W/Std. Hitch; 1998-1980; W/92" Belt O.C.; W/60" Deck	810092		6892
<b>Power King 1200 Series</b>			
Belt; Ser. No. 21299 & Before			6831
Belt; Ser. No. 21300 & After	810025		6825
<b>EVERRIDE</b>			
<b>Briggs Warrior</b>			
Blade Drive	181036		B112
Eng. To Deck	181139		6665BR
<b>EFRKW1948S</b>			
Deck Drive	TCU16092		6745BR
Hydro. Drive	D28125		6914BR
<b>EFRKW2352S</b>			
Deck Drive	TCU16093		6598BR
Hydro. Drive	D28125		6914BR
<b>EFRKW2561S</b>			
Deck Drive	GDU10228		6950BR
Hydro. Drive	D28125		6914BR
<b>EFXKA1934S</b>			
Deck Drive	201010		6815BR
<b>EFXKA1948S</b>			
Deck Drive	TCU18847		6949BR
Hydro. Drive	GDU10025		6559BR
<b>EFXKA1952S; EFXKA2352S; EFXKW2352S</b>			
Deck Drive	TCU18848		6492BR
Hydro. Drive	GDU10025		6559BR
<b>ESCKA1948S; ESKH1848S</b>			
Deck Drive	TCU18847		6949BR
Hydro. Drive	GDU10025		6559BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EVERRIDE - Continued</b>			
<b>ESKH2352S</b>			
Deck Drive .....	TCU18848		6492BR
Hydro. Drive .....	GDU10025		6559BR
<b>ESKH2561S</b>			
Deck Drive .....	TCU18849		6901BR
Hydro. Drive .....	GDU10025		6559BR
<b>ESKW1948S</b>			
Deck Drive .....	TCU18847		6949BR
Hydro. Drive .....	GDU10025		6559BR
<b>ESKW2352S</b>			
Deck Drive .....	TCU18848		6492BR
Hydro. Drive .....	GDU10025		6559BR
<b>EWRKW2754S</b>			
Blade Drive .....	181036		B112
Eng. To Deck .....	181715		6665BR
Hydro. Drive .....	181727		6943BR
<b>EWRKW2760S</b>			
Blade Drive .....	112616		B120
Eng. To Deck .....	181715		6665BR
Hydro. Drive .....	181727		6943BR
<b>EWRKW3166S</b>			
Blade Drive .....	181711		6946BR
Eng. To Deck .....	181715		6665BR
Hydro. Drive .....	181727		6943BR
<b>EYJKC1840S</b>			
Deck Drive .....	07219600		6486BR
Hydro. Drive .....	07241400		6943BR
<b>EYJKC2044S</b>			
Hydro. Drive .....	07241400		6943BR
<b>EYJKC2348S</b>			
Deck Drive .....	07200022		6978BR
Hydro. Drive .....	07241400		6943BR
<b>EZBR2548S</b>			
Deck Drive .....	191378		6906BR
<b>EZKA1948S</b>			
Deck Drive .....	191378		6906BR
Hydro. Drive .....	192111		6896BR
<b>EZKH2754S</b>			
Blade Drive .....	181036		B112
Eng. To Deck .....	181139		6665BR
<b>EZKH2760S</b>			
Blade Drive .....	112616		B120
Eng. To Deck .....	181139		6665BR
<b>EZKH2766S</b>			
Blade Drive .....	181711		6946BR
Eng. To Deck .....	181715		6665BR
Hydro. Drive .....	181727		6943BR
<b>EZKW2352S</b>			
Deck Drive; 2007 & Older .....	191379		6767BR
Deck Drive; 2008 & Newer .....	192015		6692BR
Hydro. Drive .....	192111		6896BR
<b>EZKW2554S</b>			
Blade Drive .....	181036		B112
Eng. To Deck .....	181715		6665BR
Hydro. Drive .....	181727		6943BR
<b>EZKW2560S</b>			
Blade Drive .....	112616		B120
Eng. To Deck .....	181715		6665BR
Hydro. Drive .....	181727		6943BR
<b>EZYN2048S</b>			
Deck Drive .....	191378		6906BR
Hydro. Drive .....	192111		6896BR
<b>EZYN2052S</b>			
Deck Drive .....	192015		6692BR
Hydro. Drive .....	192111		6896BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXCEL</b>			
<b>Hustler 260K</b>			
Deck .....	716910		6844
<b>Hustler 320</b>			
Fan & Alt .....		7405	
<b>Hustler 340</b>			
Fan & Alt.; W/38 1/2" Belt O.C. ....	REMF1385	7385	
Fan & Alt.; W/40 1/2" Belt O.C. ....		7405	
<b>Hustler 400</b>			
Fan & Alt .....	039289	7340	
Gov.; W/24" Belt O.C. ....		7240	
Gov.; W/42 5/8" Belt O.C. ....	046813	7425	
Gov.; W/44" Belt O.C.; Ser. No. 5872970 & After .....		7440	
<b>EXMARK</b>			
<b>EX-18KO; EX-20KO</b>			
Primary Drive; Ser. No. 102000 & After ..	523413		6943
Secondary Drive .....	513037		6942
<b>Explorer; Explorer II</b>			
Deck Drive; W/60" Side Discharge			
Deck .....	523175		6577BR
Primary Drive; Ser. No. 102000 & After ..	523413		6943
Secondary Drive .....	513037		6942
<b>EXS-18KO; EXS-20KC</b>			
Primary Drive; Ser. No. 102000 & After ..	523413		6943
Secondary Drive .....	513037		6942
<b>EXS-20KC-2</b>			
Deck Drive; W/60" Side Discharge			
Deck .....	523175		6577BR
Primary Drive; Ser. No. 102000 & After ..	523413		6943
Secondary Drive .....	513037		6942
<b>EXS-20KO</b>			
Primary Drive; Ser. No. 102000 & After ..	523413		6943
Secondary Drive .....	513037		6942
<b>FR25KD; FR27KC; FR31BV</b>			
Deck Drive; W/52" Deck .....	1-633366		6568BR
Deck Drive; W/60" Deck .....	1-633127		6567BR
Deck Drive; W/72" Deck .....	1-643052		6569BR
Hydro. Pump .....	109-0816		6931BR
P.T.O. ....	109-7588		6926BR
<b>LHP19KA465; LHP23KA465</b>			
Deck Drive .....	109-2523		6729BR
Pump .....	103-4761		6726BR
<b>LHP23KA505</b>			
Deck Drive .....	109-0206		6730BR
Pump .....	103-4761		6726BR
<b>LHP23KA565</b>			
Deck Drive .....	109-0096		6731BR
Pump .....	103-4761		6726BR
<b>LHP23KC523</b>			
Deck Drive .....	1-653368		6597BR
Pump .....	103-4761		6726BR
<b>LHP27KC505</b>			
Deck Drive .....	109-0206		6730BR
Pump .....	103-4761		6726BR
<b>LHP27KC523</b>			
Deck Drive .....	1-653368		6597BR
Pump .....	103-4761		6726BR
<b>LHP27KC565</b>			
Deck Drive .....	109-0096		6731BR
Pump .....	103-4761		6726BR
<b>LHP4417KA; LHP4418KC</b>			
Deck Drive .....	413093		6596BR
Pump Drive .....	653163		6726BR
<b>LHP4419KA; LHP4818KC; LHP4820KC; LHP4821KA</b>			
Deck Drive .....	413308		6783BR
Pump Drive .....	653163		6726BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>LHP5220KC; LHP5223KA; LHP5223KC</b>			
Deck Drive .....	653368		6597BR
Pump Drive .....	653416		6552BR
<b>LXS25KD605</b>			
Deck Drive; W/60" Deck .....	633127		6567BR
Hydro. Pump .....	103-4569		7020BR
Mule Drive .....	109-2994		6589BR
<b>LXS25KD665</b>			
Deck Drive; W/66" Deck .....	109-5018		6598BR
Hydro. Pump .....	103-4569		7020BR
Mule Drive .....	109-2994		6589BR
<b>LXS25KD725</b>			
Deck Drive; W/72" Deck .....	1-643052		6569BR
Hydro. Pump .....	103-4569		7020BR
Mule Drive .....	109-2994		6589BR
<b>LXS29LKA605</b>			
Deck Drive; W/60" Deck .....	633127		6567BR
Mule Drive .....	103-6506		6648BR
<b>LXS29LKA665</b>			
Deck Drive; W/66" Deck .....	109-0775		6598BR
Mule Drive .....	103-6506		6648BR
<b>LXS29LKA725</b>			
Deck Drive; W/72" Deck .....	1-643052		6569BR
Mule Drive .....	103-6506		6648BR
Pump Drive .....	103-4569		7020BR
<b>LXS31BV605</b>			
Deck Drive; W/60" Deck .....	633127		6567BR
Mule Drive .....	103-6506		6648BR
Pump Drive .....	103-4569		7020BR
<b>LXS31BV665</b>			
Deck Drive; W/66" Deck .....	109-0775		6598BR
Mule Drive .....	103-6506		6648BR
Pump Drive .....	103-4569		7020BR
<b>LXS35BV605</b>			
Deck Drive; W/60" Deck .....	633127		6567BR
Mule Drive .....	103-6506		6648BR
Pump Drive .....	103-4569		7020BR
<b>LXS35BV665</b>			
Deck Drive; W/66" Deck .....	109-0775		6598BR
Mule Drive .....	103-6506		6648BR
Pump Drive .....	103-4569		7020BR
<b>LXS35BV725</b>			
Deck Drive; W/72" Deck .....	1-643052		6569BR
Mule Drive .....	103-6506		6648BR
Pump Drive .....	103-4569		7020BR
<b>LZ22LKA523</b>			
Alt .....	633853		6726
Deck Drive .....	633366		6568BR
Mule Drive .....	633173		6650BR
Pump Drive .....	633569	K050565	
<b>LZ22LKA604</b>			
Alt .....	633853		6726
Deck Drive .....	633127		6567BR
Mule Drive .....	633173		6650BR
Pump Drive .....	633569	K050565	
<b>LZ23KC523</b>			
Deck Drive .....	633366		6568BR
Mule Drive .....	633173		6650BR
Pump Drive; W/5-Ribbed Belt .....	633569	K050565	
Pump Drive; W/8-Ribbed Belt .....	633162		6543BR
<b>LZ23KC604; LZ23KC605</b>			
Deck Drive .....	633127		6567BR
Mule Drive .....	103-4014		6728BR
Pump Drive .....	103-6906		6742BR
<b>LZ25KC523</b>			
Deck Drive .....	633366		6568BR
Mule Drive .....	633173		6650BR
Pump Drive; W/5-Ribbed Belt .....	633569	K050565	
Pump Drive; W/8-Ribbed Belt .....	633162		6543BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>LZ25KC604</b>			
Deck Drive .....	633127		6567BR
Mule Drive .....	633173		6650BR
Pump Drive; W/5-Ribbed Belt .....	633569	K050565	
Pump Drive; W/8-Ribbed Belt .....	633162		6543BR
<b>LZ25KC724</b>			
Deck Drive .....	643052		6569BR
Mule Drive .....	633173		6650BR
Pump; W/5-Ribbed Belt .....	633569	K050565	
Pump; W/8-Ribbed Belt .....	633162		6543BR
<b>LZ25LC604; LZ25LC724</b>			
Mule Drive .....	633173		6650BR
Pump Drive .....	633569	K050565	
<b>LZ26KC604</b>			
Deck Drive .....	633127		6567BR
Mule Drive .....	633173		6650BR
<b>LZ26KC724</b>			
Deck Drive .....	643052		6569BR
Mule Drive .....	633173		6650BR
<b>LZ26LC724</b>			
Mule Drive .....	633173		6650BR
<b>LZ27DD604</b>			
Blade Drive; W/60" Deck .....	1-633127		6567BR
Mule Drive .....	103-0881		6662BR
<b>LZ27DD724</b>			
Blade Drive; W/72" Deck .....	1-643052		6569BR
Mule Drive .....	103-0881		6662BR
<b>LZ28KC605</b>			
Deck Drive .....	1-633127		6567BR
Hydro. Pump; Ser. No. 509999 & Before .....	1-633569	K050565	
Hydro. Pump; Ser. No. 510000 & After ...	103-6906		6742BR
Mule Drive; Ser. No. 369999 & Before ...	1-633173		6650BR
Mule Drive; Ser. No. 370000 & After .....	103-4014		6728BR
<b>LZ31BV604</b>			
Mule Drive .....	103-6506		6648BR
<b>LZA20KAS484; LZA20KAX484</b>			
Deck Drive .....	116-1965		6879BR
Hydro. Drive .....	116-1953		6862BR
<b>LZA20KAX524</b>			
Deck Drive .....	116-1966		6860BR
Hydro. Drive .....	116-1953		6862BR
<b>LZAS20BV484; LZAS20KC484</b>			
Deck; W/48" Deck .....	109-8070		6879BR
Hydro. Pump .....	109-3388		6780BR
<b>LZAS22KA484</b>			
Deck Drive .....	109-8070		6879BR
Hydro. Drive .....	109-3388		6780BR
<b>LZAS23KC524</b>			
Deck; W/52" Deck .....	109-4994		6860BR
Hydro. Pump .....	109-3388		6780BR
<b>LZAS25KC604; LZAS26LKA604</b>			
Deck; W/60" Deck .....	109-8073		6850BR
Hydro. Pump .....	109-3388		6780BR
<b>LZAS27KC524</b>			
Deck; W/52" Deck .....	109-4994		6860BR
Hydro. Pump .....	109-3388		6780BR
<b>LZAS27KC604</b>			
Deck; W/60" Deck .....	109-8073		6850BR
Hydro. Pump .....	109-3388		6780BR
<b>LZAS29KA724</b>			
Deck; W/72" Deck .....	109-9023		6851BR
Hydro. Pump .....	109-3388		6780BR
<b>LZD25KD605</b>			
Deck Drive .....	1-633127		6567BR
Fan .....	109-2901	7345	
Hydro. Drive .....	109-7582		6932BR
Mule Drive .....	109-4199		6589BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>LZD25KD725</b>			
Deck Drive .....	1-643052		6569BR
Fan .....	109-2901	7345	
Hydro. Drive .....	109-7582		6932BR
Mule Drive .....	109-4199		6589BR
<b>LZDS902K60RD</b>			
Blade Drive .....	116-8187		7060BR
Fan .....	109-2901	7345	
Hydro. Drive .....	109-7582		6932BR
<b>LZDS902K72RD</b>			
Blade Drive .....	116-8501		7061BR
Fan .....	109-2901	7345	
Hydro. Drive .....	109-7582		6932BR
<b>LZDS902K605</b>			
Deck Drive .....	1-633127		6567BR
Fan .....	109-2901	7345	
Hydro. Drive .....	109-7582		6932BR
Mule Drive .....	109-4199		6589BR
<b>LZDS902K725</b>			
Deck Drive .....	1-643052		6569BR
Fan .....	109-2901	7345	
Hydro. Drive .....	109-7582		6932BR
Mule Drive .....	109-4199		6589BR
<b>LZE20KA484; LZE22KA484</b>			
Deck Drive .....	116-1965		6879BR
Hydro. Drive .....	116-1953		6862BR
<b>LZE24KA524</b>			
Deck Drive .....	116-1966		6860BR
Hydro. Drive .....	116-1953		6862BR
<b>LZE27KC604</b>			
Hydro. Drive .....	116-1953		6862BR
<b>LZE600KA484</b>			
Deck Drive .....	116-1965		6879BR
Hydro. Drive .....	116-1953		6862BR
<b>LZE651GKA484A2</b>			
Deck Drive .....	109-8070		6879BR
Hydro. Drive .....	116-1953		6862BR
<b>LZE691KA524</b>			
Deck Drive .....	116-1966		6860BR
Hydro. Drive .....	116-1953		6862BR
<b>LZE730KA604; LZE730KA604SS; LZE740EKC604; LZE740EKC60400; LZE740KC604</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZE751CKA524A2</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	116-1953		6862BR
<b>LZE751CKA604A1</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZE751GKA60RA1</b>			
Blade Drive .....	116-8187		7060BR
Eng. To Deck .....	125-9371		7058BR
Hydro. Drive .....	109-3388		6780BR
<b>LZE751GKA72RA1</b>			
Blade Drive .....	116-8501		7061BR
Eng. To Deck .....	109-8070		6879BR
Hydro. Drive .....	109-3388		6780BR
<b>LZE751GKA524A2</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	116-1953		6862BR
<b>LZE751GKA604A1</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZE751GKA724A1</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>LZS22KA484</b>			
Deck Drive .....	109-8070		6879BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS23KC524</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS25EKC604; LZS25KC604</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS27KC524</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS27KC604</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS29EKC724; LZS29KA724</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS29PKA604</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS29PKA724</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS651CKA484A2; LZS651KA484</b>			
Deck Drive .....	109-8070		6879BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS680KC524; LZS691KA524; LZS730EKC524</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS730EKC604</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS740AKC524A2</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS740EKC60RD; LZS740EKC60RS</b>			
Blade Drive .....	116-8187		7060BR
Eng. To Deck .....	125-9371		7058BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS740KC524</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS740KC604</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS740PKC524</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS740PKC604</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS740PKC724</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS740PKC52400</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS740PKC60400</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS740PKC72400</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS742KC604; LZS749AKC604A1</b>			
Deck Drive .....	109-8073		6850BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>LZS742KC604; LZS749AKC604A1 – Continued</b>			
Hydro. Drive .....	109-3388		6780BR
<b>LZS749AKC724A1; LZS749AKC72400</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS749EKC72RD; LZS749EKC72RS</b>			
Blade Drive .....	116-8501		7061BR
Eng. To Deck .....	109-8070		6879BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS749EKC604</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS749EKC724</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS801GKA524A2</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS801GKA604A1</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS801GKA724A1</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS801KA524</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS801KA604</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS801KA724</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS801PKA604</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS801PKA724</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZS850EKA604W0</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Pump .....	109-3388		6780BR
<b>LZS850EKA724W0</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Pump .....	109-3388		6780BR
<b>LZS902DKU60R00</b>			
Blade Drive .....	116-8187		7060BR
Fan .....	109-2901	7345	
Hydro. Drive .....	109-7582		6932BR
<b>LZS902DKU72R00</b>			
Blade Drive .....	116-8501		7061BR
Fan .....	109-2901	7345	
Hydro. Drive .....	109-2901	7345	
<b>LZS902DKU605A1</b>			
Blade Drive .....	1-633127		6567BR
Fan .....	109-2901	7345	
Hydro. Drive .....	109-7582		6932BR
Mule Drive .....	109-4199		6589BR
<b>LZS902DKU725A1</b>			
Blade Drive .....	1-643052		6569BR
Fan .....	109-2901	7345	
Hydro. Drive .....	109-7582		6932BR
Mule Drive .....	109-4199		6589BR
<b>LZX23KC486</b>			
Deck Drive .....	109-8070		6879BR
Hydro. Drive .....	109-3388		6780BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>LZX24KA526</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX27KC526</b>			
Deck Drive .....	109-4994		6784BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX27KC606; LZX29EKC606; LZX29KA606; LZX29PKA606; LZX34KC606</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX34KC726</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX38KC606</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX38KC726</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX680KC486</b>			
Deck Drive .....	109-8070		6879BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX740EKC526; LZX740EKC526T0;</b>			
<b>LZX740KC526</b>			
Deck Drive .....	109-4994		6860BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX740KC606; LZX749EKC606; LZX801CKA60600; LZX801KA606; LZX921GKA60600</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX921GKA72600</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX921KA606</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX921KA726</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX940EKC60RT0</b>			
Blade Drive .....	116-8187		7060BR
Eng. To Deck .....	125-9371		7058BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX940EKC72RT0</b>			
Blade Drive .....	116-8501		7061BR
Eng. To Deck .....	109-8070		6879BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX940EKC606; LZX940EKC606T0; LZX940EKC60600; LZX940KC606</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX940KC726; LZX980EKC726; LZX980EKC726T0; LZX980EKC72600</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX980KC606</b>			
Deck Drive .....	109-8073		6850BR
Hydro. Drive .....	109-3388		6780BR
<b>LZX980KC726</b>			
Deck Drive .....	109-9023		6851BR
Hydro. Drive .....	109-3388		6780BR
<b>LZZ23KA526</b>			
Deck; W/52" Deck .....	109-4994		6860BR
Hydro. Pump .....	109-3388		6780BR
<b>LZZ23KC486</b>			
Deck; W/48" Deck .....	109-8070		6879BR



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>LZZ23KC486 – Continued</b>			
Hydro. Pump .....	109-3388		6780BR
<b>LZZ23KC526; LZZ24KA526; LZZ27KC526</b>			
Deck; W/52" Deck .....	109-4994	6860BR	
Hydro. Pump .....	109-3388	6780BR	
<b>LZZ27KC606; LZZ29KA606; LZZ29KCE606; LZZ34KA606</b>			
Deck; W/60" Deck .....	109-8073	6850BR	
Hydro. Pump .....	109-3388	6780BR	
<b>LZZ34KA726</b>			
Deck; W/72" Deck .....	109-9023	6851BR	
Hydro. Pump .....	109-3388	6780BR	
<b>LZZ38KC606</b>			
Deck; W/60" Deck .....	109-8073	6850BR	
Hydro. Pump .....	109-3388	6780BR	
<b>LZZ38KC726</b>			
Deck; W/72" Deck .....	109-9023	6851BR	
Hydro. Pump .....	109-3388	6780BR	
<b>NAV20KC; NAV27KC; NV20KC; NV27EKC; NV27KC; NV640KC; NV730EKC; NV740KC; NVS730AKC48000; NVS740CKC42000</b>			
Hydro. Pump .....	103-4244	6930BR	
P.T.O. ....	103-6737	6925BR	
<b>NVS740CKC48000</b>			
Hydro. Pump .....	103-4244	6930BR	
P.T.O. ....	103-6737	6925BR	
<b>PHZ19KA343</b>			
Deck Drive .....	103-9366	6781BR	
<b>PHZ19KA443</b>			
Deck Drive .....	109-2236	6727BR	
<b>PNE22KA482</b>			
Deck Drive .....	116-3455	6719BR	
Hydro. Drive .....	115-9613	6780BR	
<b>PNE24KA522</b>			
Deck Drive .....	103-9273	6859BR	
Hydro. Drive .....	115-9613	6780BR	
<b>PNE651KA482</b>			
Deck Drive .....	116-3455	6719BR	
Hydro. Drive .....	115-9613	6780BR	
<b>PNE691KA522</b>			
Deck Drive .....	103-9273	6859BR	
Hydro. Drive .....	115-9613	6780BR	
<b>PNS20KA443</b>			
Deck Drive .....	1-413093	6596BR	
Hydro. Drive .....	115-9613	6780BR	
<b>PNS22KA483</b>			
Deck Drive .....	116-3455	6719BR	
Hydro. Drive .....	115-9613	6780BR	
<b>PNS24KA523</b>			
Deck Drive .....	103-9273	6859BR	
Hydro. Drive .....	115-9613	6780BR	
<b>PNS600KA443</b>			
Deck Drive .....	1-413093	6596BR	
Hydro. Drive .....	115-9613	6780BR	
<b>PNS651KA483</b>			
Deck Drive .....	116-3455	6719BR	
Hydro. Drive .....	115-9613	6780BR	
<b>PNS680KC523; PNS691KA523</b>			
Deck Drive .....	103-9273	6859BR	
Hydro. Drive .....	115-9613	6780BR	
<b>PNS710KC443</b>			
Deck Drive .....	1-413093	6596BR	
Hydro. Drive .....	115-9613	6780BR	
<b>PNS710KC483</b>			
Deck Drive .....	116-3455	6719BR	
Hydro. Drive .....	115-9613	6780BR	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>PNS720KC523</b>			
Deck Drive .....	103-9273		6859BR
Hydro. Drive .....	115-9613		6780BR
<b>PNS730KA604; PNS740KC604; PNS740KC604SS</b>			
Deck Drive .....	114-8154		6802BR
Hydro. Drive .....	115-9613		6780BR
<b>QSP20KAS443</b>			
Deck Drive .....	1-413093		6596BR
Hydro. Drive .....	115-9613		6780BR
<b>QSP20KAS483</b>			
Deck Drive .....	116-3455		6719BR
Hydro. Drive .....	115-9613		6780BR
<b>QSP22KAS523</b>			
Deck Drive .....	103-9273		6859BR
Hydro. Drive .....	115-9613		6780BR
<b>QSS708GEM42200</b>			
Deck Drive .....	119-8819		6872BR
<b>QSS708GEM50200</b>			
Deck Drive .....	119-8820		6873BR
<b>QST20BE422</b>			
Deck Drive .....	108-6645		6849BR
Hydro. Pump .....	115-9613		6780BR
<b>QST22BE482</b>			
Deck Drive .....	109-5364		6708BR
Hydro. Pump .....	109-3388		6780BR
<b>QST24BE522</b>			
Deck Drive .....	109-3661		6782BR
Hydro. Pump .....	109-3388		6780BR
<b>QT22KA421</b>			
Deck Drive .....	119-8819		6872BR
Hydro. Drive .....	119-3309		6887BR
<b>QT24KA501</b>			
Deck Drive .....	119-8820		6873BR
Hydro. Drive .....	119-3321		6888BR
<b>QTE452CEM42100</b>			
Deck Drive .....	119-8819		6872BR
<b>QTE651KA421</b>			
Deck Drive .....	119-8819		6872BR
Hydro. Drive .....	119-3309		6887BR
<b>QTE691KA501</b>			
Deck Drive .....	119-8820		6873BR
Hydro. Drive .....	119-3321		6888BR
<b>QTE708GEM42200</b>			
Deck Drive .....	119-8819		6872BR
<b>QTE708GEM50200</b>			
Deck Drive .....	119-8820		6873BR
<b>QTS452CEM34200</b>			
Deck Drive .....	130-0842		6810BR
<b>QTS691KA422</b>			
Deck Drive .....	119-8819		6872BR
Hydro. Drive .....	119-3309		6887BR
<b>QTS691KA502</b>			
Deck Drive .....	119-8820		6873BR
Hydro. Drive .....	119-3321		6888BR
<b>QTS708GEM42200</b>			
Deck Drive .....	119-8819		6872BR
<b>QTS708GEM50200</b>			
Deck Drive .....	119-8820		6873BR
<b>QZE708GEM34200</b>			
Deck Drive .....	130-0842		6810BR
<b>QZE708GEM42200</b>			
Deck Drive .....	119-8819		6872BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>RAE708GEM48300</b>			
Deck Drive .....	126-6626		6997BR
<b>Ranger 48"</b>			
Spindle - Left .....	DH3012		6952
<b>RAS708GEM60RC3</b>			
Blade Drive .....	116-8187		7060BR
<b>RAS710CKC48300</b>			
Deck Drive .....	126-6626		6997BR
<b>RAS740GKC60R00</b>			
Blade Drive .....	116-8187		7060BR
<b>RAX651GKA484A3</b>			
Deck Drive .....	126-6626		6997BR
<b>TR-17K</b>			
Cross Deck; W/52" Deck .....	603576		6480BR
Cross Deck; W/60" Deck .....	603045		6928BR
Deck Drive; W/52" Deck .....	543749		6649BR
Deck Drive; W/60" Deck .....	303080		6614BR
Trans. ....	543548		6837
<b>TR-18KC</b>			
Cross Deck; W/52" Deck .....	603576		6480BR
Deck Drive; W/52" Deck .....	543749		6649BR
Trans. ....	543548		6837
<b>TR-18KO; TR-20KO; TR-22KC</b>			
Cross Deck; W/52" Deck .....	603576		6480BR
Cross Deck; W/60" Deck .....	603045		6928BR
Deck Drive; W/52" Deck .....	543749		6649BR
Deck Drive; W/60" Deck .....	303080		6614BR
Trans. ....	543548		6837
<b>TR-23KC</b>			
Cross Deck; W/FMD-52, FMD-523 Deck .....	603576		6480BR
Cross Deck; W/FMD-60, FMD-603 Deck .....	603045		6928BR
Eng. To Deck; W/FMD52 Deck; Ser. No. 115000 & After .....	543749		6649BR
Eng. To Deck; W/FMD52 Deck; Ser. No. 83999 & Before .....	543898		6991
Eng. To Deck; W/FMD52 Deck; Ser. No. 84000-114999 .....	543028		6649BR
Eng. To Deck; W/FMD523 Deck .....	543749		6649BR
Eng. To Deck; W/FMD60 Deck; Ser. No. 89999 & Before .....	543521		6987
Eng. To Deck; W/FMD60 Deck; Ser. No. 90000 & After .....	543523		6839BR
Eng. To Deck; W/FMD603 Deck .....	543523		6839BR
Trans.; W/52", 60" Deck .....	543548		6837
<b>VT18KA363</b>			
Deck Drive .....	116-3703		6924BR
Hydro. Drive .....	119-0174		6922BR
<b>VT20KA484; VT24KA484</b>			
Deck Drive .....	99-4627		6767BR
Hydro. Drive .....	119-0174		6922BR
<b>VT24KA524; VT25EKC524</b>			
Deck Drive .....	116-3111		6598BR
Hydro. Drive .....	119-0174		6922BR
<b>VT541KA363</b>			
Deck Drive .....	116-3703		6924BR
Hydro. Drive .....	119-0174		6922BR
<b>VT651KA484</b>			
Deck Drive .....	99-4627		6767BR
Hydro. Drive .....	114567		6927BR
<b>VT691KA524; VT730EKC524</b>			
Deck Drive .....	116-3111		6598BR
Hydro. Drive .....	114567		6927BR
<b>VT740EKC604</b>			
Deck Drive .....	99-4627		6767BR
Hydro. Drive .....	114567		6927BR
<b>VTS541CKA36300; VTS541KA363</b>			
Deck Drive .....	116-3703		6924BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>VTS541CKA36300; VTS541KA363 - Continued</b>			
Hydro. Drive .....	119-0174		6922BR
<b>VTS651KA484; VTS691CKA48400</b>			
Deck Drive .....	99-4627		6767BR
Hydro. Drive .....	114567		6927BR
<b>VTS691CKA52400; VTS691KA524; VTS730AKC52400; VTS730EKC524</b>			
Deck Drive .....	116-3111		6598BR
Hydro. Drive .....	114567		6927BR
<b>VTS740EKC604; VTS740EKC60400</b>			
Deck Drive .....	99-4627		6767BR
Hydro. Drive .....	114567		6927BR
<b>VTS740PKC52400</b>			
Deck Drive .....	116-3111		6598BR
Hydro. Drive .....	114567		6927BR
<b>VTS740PKC60400; VTX651GKA48400; VTX651KA484</b>			
Deck Drive .....	99-4627		6767BR
Hydro. Drive .....	114567		6927BR
<b>VTX691KA524; VTX730EKC524; VTX730EKC52400</b>			
Deck Drive .....	116-3111		6598BR
Hydro. Drive .....	114567		6927BR
<b>VTX740EKC604; VTX740EKC60400</b>			
Deck Drive .....	99-4627		6767BR
Hydro. Drive .....	114567		6927BR
<b>FALLS</b>			
<b>CPR22-100; R22-113; R2250</b>			
Belt .....	151850	2280	6828
<b>FERRIS INDUSTRIES, INC.</b>			
<b>1000ZKAV21/48</b>			
Pump .....	5022314		6559BR
<b>1000ZKAV23/52</b>			
Deck .....	5022148		6746BR
Pump .....	5022314		6559BR
<b>1000ZKAV23/61</b>			
Deck; Ser. No. 2898 & Before .....	5022061		6661BR
Deck; Ser. No. 2899 & After .....	5023386		6770BR
Pump .....	5022314		6559BR
<b>EVKAV2048</b>			
Blade Drive .....	5101121		6877BR
<b>EVKAV2252</b>			
Blade Drive .....	5102035		6858BR
Eng. To Deck .....	5102040		6615BR
Pump .....	5100555		6772BR
<b>EVKAV2648</b>			
Blade Drive .....	5101121		6877BR
<b>EVKAV2652</b>			
Blade Drive .....	5102035		6858BR
Eng. To Deck .....	5102040		6615BR
Pump .....	5100555		6772BR
<b>EVKAV2748</b>			
Blade Drive .....	5101121		6877BR
<b>F160ZBV2648</b>			
Deck Drive .....	5103392		6999BR
Transaxle .....	5102767		6996BR
<b>F160ZBVE2852</b>			
Deck Drive .....	5103872		6936BR
Transaxle .....	5102767		6996BR
<b>F160ZKAV2448</b>			
Deck Drive .....	5103392		6999BR
Transaxle .....	5102767		6996BR
<b>F160ZKAV2452</b>			
Deck Drive .....	5103872		6936BR
Transaxle .....	5102767		6996BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FERRIS INDUSTRIES, INC. - Continued</b>			
<b>F210BVE2861; F210ZKAV2661</b>			
Deck Drive .....	5103870		6937BR
Transaxle .....	5102013		6506BR
<b>F320ZBVE3761</b>			
Deck Drive .....	5103871		6938BR
Transaxle .....	5102013		6506BR
<b>F320ZBVE3772</b>			
Deck Drive .....	5104059		7111BR
Transaxle .....	5102013		6506BR
<b>F320ZKAV3561</b>			
Deck Drive .....	5103871		6938BR
Transaxle .....	5102013		6506BR
<b>F320ZKAV3572</b>			
Deck Drive .....	5104059		7111BR
Transaxle .....	5102013		6506BR
<b>F800XBV31</b>			
Deck Drive; W/61" Deck .....	5021854		6946BR
Deck Drive; W/72" Deck .....	5022435		6933BR
P.T.O. ....	5101179		6974BR
Pump Drive .....	5102695		6820BR
<b>F800XY30D</b>		9400	9400HD
Alt. ....	5101985X5		6946BR
Deck Drive; W/61" Deck .....	5021854		6933BR
Deck Drive; W/72" Deck .....	5022435		6974BR
P.T.O. ....	5102594		7023BR
Pump Drive .....	5102039		
<b>H2224KAV</b>			
Deck Drive .....	5100046		6878BR
Pump; Ser. No. 2015675570 & Before ...	5100808		7040BR
<b>H2225KAV61; H2226B61</b>			
Deck Drive .....	5100046		6878BR
Pump .....	5100808		7040BR
<b>H2226KAV</b>			
Deck Drive; W/61" Deck .....	5100046		6878BR
Pump .....	5100808		7040BR
<b>H2227B</b>			
Deck Drive; W/61" Deck .....	5100046		6878BR
Pump; Ser. No. 2015675570 & Before ...	5100808		7040BR
<b>H2227K61</b>			
Deck Drive .....	5100046		6878BR
Pump .....	5100808		7040BR
<b>H2228B</b>			
Deck Drive .....	5100046		6878BR
Pump; Ser. No. 2015675570 & Before ...	5100808		7040BR
<b>H3225K</b>			
Deck Drive; W/72" Deck .....	5021724		6934BR
Spindle; W/61" Deck .....	5020824		6748BR
<b>IS500Z</b>			
Eng. To Deck; W/44" Deck .....	5023496		6599BR
Eng. To Deck; W/52" Deck .....	5023304		6769BR
Eng. To Deck; W/61" Deck .....	5023386		6770BR
Hydro. Drive .....	5100923		6482BR
<b>IS500ZB2444</b>			
Deck Drive .....	5023496		6599BR
Pump Drive .....	5100923		6482BR
<b>IS500ZB2752</b>			
Deck Drive .....	5023304		6769BR
Pump Drive .....	5100923		6482BR
<b>IS500ZB2761</b>			
Deck Drive .....	5023386		6770BR
Pump Drive .....	5100923		6482BR
<b>IS600ZB2544; IS600ZB2548; IS600ZKAV1948; IS600ZKAV19744</b>			
Transaxle .....	5103885		6923BR
<b>IS700ZB2661</b>			
Deck Drive .....	5103871		6938BR
Transaxle .....	5103653		6684BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FERRIS INDUSTRIES, INC. - Continued</b>			
<b>IS700ZB2752</b>			
Deck Drive .....	5103927		7000BR
Transaxle .....	5103653		6684BR
<b>IS700ZB2761; IS700ZBV2661</b>			
Deck Drive .....	5103871		6938BR
Transaxle .....	5103653		6684BR
<b>IS700ZKAV2352</b>			
Deck Drive .....	5103927		7000BR
Transaxle .....	5103653		6684BR
<b>IS700ZKAV2461; IS700ZKAVE2661</b>			
Deck Drive .....	5103871		6938BR
Transaxle .....	5103653		6684BR
<b>IS1000ZKAV21/48</b>			
Pump .....	5022314		6559BR
<b>IS1000ZKAV23/52</b>			
Deck .....	5022148		6746BR
Pump .....	5022314		6559BR
<b>IS1500Z</b>			
Eng. To Deck; W/44" Deck .....	5023496		6599BR
Eng. To Deck; W/48" Deck .....	5023297		6767BR
Eng. To Deck; W/52" Deck .....	5023435		6768BR
Eng. To Deck; W/61" Deck .....	5022061		6661BR
Hydro. Drive .....	5100555		6772BR
<b>IS1500ZB2644</b>			
Deck Drive .....	5023496		6599BR
Pump .....	5100555		6772BR
<b>IS1500ZB2648</b>			
Deck Drive .....	5023297		6767BR
Pump .....	5100555		6772BR
<b>IS1500ZKAV1944</b>			
Deck Drive .....	5023496		6599BR
Pump .....	5100555		6772BR
<b>IS1500ZKAV1948</b>			
Deck Drive .....	5023297		6767BR
Pump .....	5100555		6772BR
<b>IS1500ZKAV2044</b>			
Deck Drive .....	5023496		6599BR
Pump .....	5100555		6772BR
<b>IS1500ZKAV2048</b>			
Deck Drive .....	5023297		6767BR
Pump .....	5100555		6772BR
<b>IS1500ZXB2652</b>			
Deck Drive .....	5103395		6936BR
Pump .....	5100555		6772BR
<b>IS1500ZXB2861</b>			
Deck Drive .....	5103391		6938BR
Pump .....	5100555		6772BR
<b>IS1500ZXBV2861</b>			
Deck Drive; 2010 & Older .....	5022061		6661BR
Deck Drive; 2011 & Newer .....	5103391		6938BR
Hydro. Drive .....	5100555		6772BR
<b>IS1500ZXKAV2252; IS1500ZXKAV2352</b>			
Deck Drive .....	5103395		6936BR
Pump .....	5100555		6772BR
<b>IS1500ZXKAV2461</b>			
Deck Drive .....	5103391		6938BR
Pump .....	5100555		6772BR
<b>IS1500ZXKAV2652</b>			
Deck Drive .....	5103395		6936BR
Pump .....	5100555		6772BR
<b>IS1500ZXKAV2661</b>			
Deck Drive .....	5103391		6938BR
Pump .....	5100555		6772BR
<b>IS2000ZB2852</b>			
Deck Drive .....	5103395		6936BR
Pump .....	5100555		6772BR

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FERRIS INDUSTRIES, INC. - Continued</b>			
<b>IS2000ZB3061</b>			
Deck Drive .....	5103391		6938BR
Pump .....	5100555		6772BR
<b>IS2000ZBV3061SS</b>			
Deck Drive .....	5022061		6661BR
Pump .....	5100555		6772BR
<b>IS2000ZBV3261</b>			
Deck Drive .....	5103391		6938BR
Pump .....	5100555		6772BR
<b>IS2000ZK2752</b>			
Deck Drive .....	5100003		6760BR
Pump .....	5100555		6772BR
<b>IS2000ZK2761</b>			
Deck Drive .....	5022061		6661BR
Pump .....	5100555		6772BR
<b>IS2000ZKAV25/61</b>			
Eng. To Deck; W/61" Deck .....	5022061		6661BR
Hydro. Drive; W/61" Deck .....	5100555		6772BR
<b>IS2000ZKAV2552</b>			
Deck Drive .....	5100003		6760BR
Pump .....	5100555		6772BR
<b>IS2000ZKAV2652</b>			
Deck Drive .....	5103395		6936BR
Pump .....	5100555		6772BR
<b>IS2000ZKAV2661</b>			
Deck Drive .....	5103391		6938BR
Pump .....	5100555		6772BR
<b>IS2000ZKAV2761; IS2000ZKAV3461SS;</b>			
<b>IS2000ZLKAV2661</b>			
Deck Drive .....	5022061		6661BR
Pump .....	5100555		6772BR
<b>IS2100KOH2761</b>			
Transaxle .....	5103907		6589BR
<b>IS2100ZBV2652</b>			
Deck Drive .....	5103927		7000BR
Transaxle .....	5103907		6589BR
<b>IS2100ZBV2661; IS2100ZBV3261</b>			
Transaxle .....	5103907		6589BR
<b>IS2100ZBVE2852</b>			
Deck Drive .....	5103927		7000BR
Transaxle .....	5103907		6589BR
<b>IS2100ZBVE2861</b>			
Transaxle .....	5103907		6589BR
<b>IS2100ZKAV2652</b>			
Deck Drive .....	5103927		7000BR
Transaxle .....	5103907		6589BR
<b>IS2100ZKAV2661</b>			
Transaxle .....	5103907		6589BR
<b>IS2500ZY20D52</b>			
Deck Drive; W/Rear Discharge .....	5102269		6880BR
Deck Drive; W/Side Discharge .....	5101825		6902BR
Eng. To P.T.O. ....	5102038		7010BR
Pump .....	5102272		7035BR
<b>IS2500ZY24D61</b>		9400	9400HD
Alt. ....	5101985X5		6880BR
Deck Drive; W/Rear Discharge .....	5102269		6902BR
Deck Drive; W/Side Discharge .....	5101825		7010BR
Eng. To P.T.O. ....	5102038		7035BR
Pump .....	5102272		
<b>IS3000ZKAV23/61; IS3000ZKAV25/61</b>			
Deck .....	5022061		6661BR
Pump .....	5022314		6559BR
<b>IS3100ZBV3061; IS3100ZBV3261</b>			
Deck Drive .....	5022061		6661BR
<b>IS3100ZBV3272</b>			
Deck Drive .....	5100423		7111BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FERRIS INDUSTRIES, INC. - Continued</b>			
<b>IS3100ZBV3661</b>			
Deck Drive .....	5103390		6937BR
<b>IS3100ZBV3672</b>			
Deck Drive .....	5100423		7111BR
<b>IS3100ZBVP3261</b>			
Deck Drive .....	5022061		6661BR
<b>IS3100ZBVP3272</b>			
Deck Drive .....	5100423		7111BR
<b>IS3100ZKAV3761SS</b>			
Deck Drive .....	5022061		6661BR
<b>IS3100ZKAV3772SS</b>			
Deck Drive .....	5100423		7111BR
<b>IS3100ZLKAV2661</b>			
Deck Drive .....	5022061		6661BR
<b>IS3200KAV3761</b>			
Transaxle .....	5104378		6568BR
<b>IS3200ZBV3261</b>			
Blade Drive .....	5104780		6406BR
Transaxle .....	5104378		6568BR
<b>IS3200ZBV3272</b>			
Blade Drive .....	5105036		6644BR
Eng. To Deck .....	5105035		7110BR
Transaxle .....	5104378		6568BR
<b>IS3200ZBV3661</b>			
Transaxle .....	5104378		6568BR
<b>IS3200ZBV3672</b>			
Deck Drive .....	5104059		7111BR
Transaxle .....	5104378		6568BR
<b>IS3200ZBVE3761</b>			
Blade Drive .....	5104780		6406BR
Transaxle .....	5104378		6568BR
<b>IS3200ZBVE3772</b>			
Blade Drive .....	5105036		6644BR
Eng. To Deck .....	5105035		7110BR
Transaxle .....	5104378		6568BR
<b>IS3200ZKAV3561</b>			
Blade Drive .....	5104780		6406BR
Transaxle .....	5104378		6568BR
<b>IS3200ZKAV3572</b>			
Blade Drive .....	5105036		6644BR
Eng. To Deck .....	5105035		7110BR
Transaxle .....	5104378		6568BR
<b>IS3200ZKAV3772</b>			
Deck Drive .....	5104059		7111BR
Transaxle .....	5104378		6568BR
<b>IS4000Z/D31</b>			
Deck; W/72" Deck; Ser. No. 101 Thru			
375 .....	22439		6771BR
Deck; W/72" Deck; Ser. No. 376 &			
After .....	5022854		6935BR
Pump .....	22314		6559BR
<b>IS4000ZKAV27/61</b>			
Pump .....	22314		6559BR
<b>IS4500ZBL3561</b>			
Blade To Blade .....	5100003		6760BR
Eng. To Deck .....	5023297		6767BR
Pump .....	5023388		6941BR
<b>IS4500ZBL3572</b>			
Eng. To Deck .....	5100046		6878BR
Pump .....	5023388		6941BR
<b>IS4500ZC28D61</b>			
Blade To Blade; W/Rear Discharge .....	5100014		6893BR
Blade To Blade; W/Side Discharge .....	5023304		6769BR
Eng. To Deck .....	5023297		6767BR
Pump .....	5023388		6941BR

©Two Required

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FERRIS INDUSTRIES, INC. - Continued</b>			
<b>IS5000Z/C31D</b>			
Clutch .....	5022575		6939BR
Deck Drive; W/72" Deck .....	5022439		6771BR
Pump .....	5022314		6559BR
<b>IS5100Z/C33D61; IS5100Z/C33D61R</b>			
Deck Drive .....	5021724		6934BR
P.T.O. ....	5022575		6939BR
Pump .....	5023388		6941BR
<b>IS5100Z/C33D72; IS5100Z/C33D72R</b>			
Deck Drive; 2010 & Older .....	5022439		6771BR
Deck Drive; 2011 & Newer .....	5022854		6935BR
P.T.O. ....	5022575		6939BR
Pump .....	5023388		6941BR
<b>IS5100ZC33D</b>			
Deck Drive; W/61" Deck .....	5104067		6850BR
P.T.O. ....	5022575		6939BR
Pump Drive .....	5023388		6941BR
<b>SRSZ2BVE2852</b>			
Deck Drive .....	5104378		6568BR
Transaxle .....	5104590		7091BR
<b>SRSZ2BVE2861</b>			
Deck Drive .....	5104064		7107BR
Transaxle .....	5104590		7091BR
<b>SRSZ2KAV2652</b>			
Deck Drive .....	5104378		6568BR
Transaxle .....	5104590		7091BR
<b>SRSZ2KAV2661</b>			
Deck Drive .....	5104064		7107BR
Transaxle .....	5104590		7091BR
<b>SRSZ2KAVE2652</b>			
Deck Drive .....	5104378		6568BR
Transaxle .....	5104590		7091BR
<b>SRSZ2KAVE2661</b>			
Deck Drive .....	5104064		7107BR
Transaxle .....	5104590		7091BR
<b>FIRESTONE</b>			
<b>08-06-401</b>			
Blade .....	754935	2310	6831
Trans. ....	754936		6847
<b>08-06-501-2; 08-06-502-0; 08-06-503-9; 08-06-504-7</b>			
Blade .....	754138	3500	6950
Trans. ....	754101		6517BR
<b>08-06-505-5</b>			
Blade .....	754147	3520	6952
Trans. ....	754136		6931
Variable Speed .....	754135		6925
<b>08-06-506-3</b>			
Blade .....	754107		6830
Drive .....	754936		6847
<b>08-06-507-1; 08-06-509-8; 08-06-550-1</b>			
Blade .....	754138	3500	6950
Trans. ....	754101		6517BR
<b>08-06-705-6</b>			
Blade .....	754147	3520	6952
Trans. ....	754136		6931
Variable Speed .....	754135		6925
<b>08-06-706-6</b>			
Blade .....	754138	3500	6950
Drive .....	754164	2630	6863
<b>08-06-803-8</b>			
Blade .....	754118		6963
Trans. ....			6959
<b>08-06-804-6</b>			
Blade .....	754145		6488BR
Trans. ....	754136		6931
Variable Speed .....	754147	3520	6952

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FIRESTONE - Continued</b>			
<b>08-06-809-7</b>			
Blade .....	754127		6966
Drive; W/25" Belt O.C. ....	754135		6925
Drive; W/31" Belt O.C. ....	754136		6931
<b>08-06-813-5</b>			
Blade .....	754178	3820	6982
Drive .....	754185		6849
<b>08-06-814-3</b>			
Blade .....	754145		6488BR
Drive .....	754173	3370	6937
<b>08-06-815-1</b>			
Blade .....	754151		6967
Drive; W/31" Belt O.C. ....	754136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>08-07-201; 08-07-204; 08-07-205</b>			
Gen. ....	7540134	7330	
Trans. ....	754112	3800	6980
<b>08-07-301-5</b>			
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>08-07-302-3</b>			
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>08-07-400-3; 08-07-426-7</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>08-07-451-8</b>			
Drive .....	754124		6857
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>08-07-452-6</b>			
P.T.O. ....	754124		6857
<b>08-510-1</b>			
Blade .....	754147	3520	6952
Trans. ....	754136		6931
Variable Speed .....	754135		6925
<b>422-3-382</b>			
Blade .....	754138	3500	6950
Drive .....	754164	2630	6863
<b>422-3-423</b>			
Blade .....	754147	3520	6952
Trans. ....	754136		6931
Variable Speed .....	754135		6925
<b>422-3-430</b>			
Blade .....	754127		6966
Drive; W/25" Belt O.C. ....	754135		6925
Drive; W/31" Belt O.C. ....	754136		6931
<b>422-3-445</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540179		6950
<b>422-3-470; 422-3-475</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>422-3-495</b>			
Blade .....	7540145		6488BR
Trans. ....	7540127		6966
<b>422-5-384</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>422-5-960</b>			
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>423-3-760</b>			
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FLO-MOW</b>				<b>FORD - Continued</b>			
<b>Jet X 2668</b>				<b>140 (53265)</b>			
Spindle .....		3230		Trans. ....	342660	3770	
Transaxle .....		2600	6860				
<b>Jet X 2668-70</b>				<b>145; 165; 195</b>			
Spindle .....			6925	Drive .....	330559		6946
Transaxle; W/60" Belt O.C. ....		2600	6860	Starter .....	343031		6735
Transaxle; W/61" Belt O.C. ....		2610	6861				
<b>Jet X 2668-71; Jet X 2668-73</b>				<b>2103; 2105; 2106; 2107; 2198; 2199</b>			
Spindle .....			6925	Primary .....	210752		6870
Transaxle .....		2610	6861	Secondary; W/31" Belt O.C. ....	210753		6831
				Secondary; W/33" Belt O.C. ....	236705		6833
<b>FORD</b>				<b>2201; 2202; 2203; 2204; 2205; 2206; 2207; 2208; 2209</b>			
<b>09GN-2051; 09GN-2052; 09GN-2053</b>				Blade .....	234360		68100
Belt; W/30" Deck .....	231511		6873	Trans. ....	234110		6850
Mower Drive .....	240773		6874				
Trans. ....			3VX450	<b>2865</b>			
				Trans. ....	308511	2380	6838
<b>09GN-2054; 09GN-2055; 09GN-2056</b>				<b>2883; 2884; 2886</b>			
Mower Drive .....	240773		6874	Transaxle .....	308491		6731
Trans. ....			3VX450				
<b>09GN-2103; 09GN-2105; 09GN-2106; 09GN-2107; 09GN-2111</b>				<b>3598</b>			
Primary .....	210752		6870	Blade .....	234360		68100
				Trans. ....	234110		6850
<b>09GN-2151; 09GN-2152</b>				<b>5354; 5366</b>			
Traction .....	216594		6378	Blade .....	308476		6870
				Trans. ....	308475		6831
<b>09GN-2153</b>				<b>5371</b>			
Deck .....	216594		6378	Blade .....	308494		6866
Primary .....	210752		6870	Trans. ....	308506		6731
<b>09GN-2154</b>				<b>5372; 5373</b>			
Primary .....	210752		6870	Blade .....	308493		6869
Secondary .....	236705		6833	Trans. ....	308506		6731
<b>09GN-2155</b>				<b>5555</b>			
Deck .....	216594		6378	Blade .....	308481		6853
Primary .....	210752		6870	Trans. ....	308480		6835
<b>09GN-2198; 09GN-2199</b>				<b>5870</b>			
Primary .....	210752		6870	Blade .....	308494		6866
				Trans. ....	308506		6731
<b>09GN-2201; 09GN-2203; 09GN-2209</b>				<b>5873; 5874</b>			
Drive .....	234110		6850	Blade .....	308493		6869
				Trans. ....	308506		6731
<b>09GN-231511</b>				<b>9607430; 9607431</b>			
Belt; W/30" Deck .....	231511		6873	Trans. ....	216594		6378
<b>14 H.P.; 16 H.P.</b>				<b>9607436; 9607437; 9607438; 9607479</b>			
Fan & Alt. ....	SBA080109035	7280		Belt; W/30" Deck .....	240773		6874
<b>70 (A53110); 70 (A53111); 75 (A53115); 75 (A53116); 75 (A53117)</b>				<b>CM224</b>			
P.T.O. ....	332051		6829	Fan & Alt. ....	M30		6730
<b>80 (53055); 80 (53057); 80 (53062)</b>				<b>LGT14D</b>			
Gen. ....	315402		6832	Fan & Alt.; W/14 H.P. 3-Cyl. Diesel			
Trans. ....	342660	3770		Eng. ....	FM28	7280	
<b>85 (A53135)</b>				<b>LGT18H</b>			
P.T.O. ....	332051		6829	P.T.O. To Deck .....	LB234292035		6993
<b>100 (53056); 100 (53059); 100 (53064); 100 (53066); 100 (53078)</b>				<b>LGT100; LGT120</b>			
Trans. ....	342660	3770		Trans. ....	330559		6946
<b>100 (53083)</b>				<b>LGT125</b>			
Trans. ....	343359		6972	Deck .....	328891		6377
<b>100</b>				<b>LGT145; LGT165</b>			
Drive .....	330559		6946	Drive; Snow Blower Attachment .....	330599		6835
Starter .....	343031		6735	<b>LT11; LT12; LT12H</b>			
<b>120 (53089)</b>				Blade .....	213676		6885
Gen. ....	326227	7350		<b>LT75</b>			
Trans. ....	343359		6972	Deck .....	329193		6890
<b>120 (53091); 120 (53093); 120 (53250)</b>				P.T.O. ....	332051		6829
Gen. ....	326227	7350		Trans. ....	329184	2840	6884
Trans. ....	342660	3770		<b>LT80</b>			
<b>120; 125</b>				Eng. To Trans. ....	09JC3152		6882
Drive .....	330559		6946	<b>LT100</b>			
Starter .....	343031		6735	Blade .....	84830		6883

Lawn & Garden Equipment





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FORD - Continued</b>			
<b>LT100 - Continued</b>			
Mower Drive; W/42" Deck; W/38" Belt O.C. ....	390006		6838
Mower Drive; W/42" Deck; W/47" Belt O.C. ....	390008		6847
P.T.O. ....	336219		6830
Trans. ....	329184	2840	6884
<b>RMT50</b>			
Deck .....	308481		6853
Trans. ....	308480		6835
<b>RMT51</b>			
Deck .....	308494		6866
Trans. ....	308491		6731
<b>RMT60; RMT65</b>			
Blade; W/69" Belt O.C. ....	308493		6869
Blade; W/70" Belt O.C. ....	308476		6870
<b>RT8</b>			
Belt; W/30" Deck .....	231511		6873
<b>T800 (Riding)</b>			
P.T.O. ....	332051		6829
Starter/Gen. ....	315402		6832
Traction .....	329184	2840	6884
Trans. ....		3780	6978
<b>T1000</b>			
Gen. ....	326227	7350	
Trans. ....	326217	3810	6981
<b>YT16</b>			
Deck .....	235000		6950
Trans. ....	216594		6378
<b>G. MCNEW CO.</b>			
<b>138-340</b>			
Blade .....	7540935		6831
Transaxle .....	7540936		6847
<b>138-460</b>			
Blade .....	7540118		6963
Transaxle .....	7540937		6959
<b>G.A.C.</b>			
<b>9-1461</b>			
Blade .....	7540127		6966
Variator To Trans. ....	7540136		6931
<b>9-1465</b>			
Blade .....	7540127		6966
Trans. ....	7540166		6962
<b>9-1466</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540138		6950
Variator To Trans. ....	7540136		6931
<b>91-1460</b>			
Blade .....	7540138		6950
Trans. ....	7540101		6517BR
<b>132-242-011</b>			
Blade .....	7540127		6966
Variator To Trans. ....	7540136		6931
<b>132-412-011</b>			
Blade .....	7540138		6950
Trans. ....	7540101		6517BR
<b>132-465-011</b>			
Blade .....	7540127		6966
Trans. ....	7540166		6962
<b>132-495-011</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540138		6950
Variator To Trans. ....	7540136		6931
<b>GAMBLE SKOGMO</b>			
<b>56-032-0340</b>			
Blade .....	530050038		6862

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GAMBLE SKOGMO - Continued</b>			
<b>56-032-0340 - Continued</b>			
Drive .....	530050003		6851
<b>56-032-0341</b>			
Blade .....	530050038		6862
Drive .....	530050012		6856
Transaxle .....	530050001		6831
<b>134-501</b>			
Blade .....	7540249		6930
Trans. ....	7540264		6639BR
<b>134-504</b>			
Eng. To Deck .....	7540264		6639BR
Primary Variator .....	7540241		6494BR
Secondary Variator .....	7540240		6511BR
<b>134-669</b>			
Belt; W/39" Belt O.C. ....	7540271		6557BR
Belt; W/85" Belt O.C. ....	7540266		6775BR
<b>134-698</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>140-660</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>140-760</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>140-820; 140-830A</b>			
Drive .....	7540245		6859
Transaxle .....	7540244		6840
<b>140-960</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>140-990A</b>			
P.T.O. ....	7540165		6834
<b>142-669</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>142-960</b>			
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>143-660; 143-760</b>			
Blade .....	7540181		7014BR
Deck .....	7540180		6510BR
Drive .....	754182	3810	6981
Gen. ....	7540134	7330	
<b>143-860; 143-960</b>			
Clutch .....	754124		6857
Drive .....	7540125		6428BR
P.T.O. ....	754165		6834
<b>143-990</b>			
P.T.O. ....	7540165		6834
<b>144-660; 144-672; 144-760; 144-761</b>			
Blade .....	7540181		7014BR
Deck .....	7540180		6510BR
Drive .....	754182	3810	6981
Gen. ....	7540134	7330	
<b>144-834</b>			
Deck; W/56" Belt O.C. ....	7540230		6755BR
Deck; W/74" Belt O.C. ....	7540293		6501BR
Drive .....	7540245		6859
Transaxle .....	7540244		6840
<b>144-860</b>			
Clutch .....	754124		6857
Drive .....	7540125		6428BR
P.T.O. ....	754165		6834
<b>144-918</b>			
P.T.O. ....	7540227		6963
Trans. ....	7540212		6945





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GAMBLE SKOGMO - Continued</b>			
<b>144-960; 144-990</b>			
Clutch .....	754124		6857
Drive .....	7540125		6428BR
P.T.O. ....	754165		6834
<b>144-995</b>			
P.T.O. ....	7540234		6841
<b>146-990A</b>		7355	
Gen. ....	7540169		6834
P.T.O. ....	7540165		
<b>147-912A; 147-918A</b>			
P.T.O. ....	7540214		6850
Transaxle .....	7540212		6945
Variable Speed .....	7540210		6960
<b>147-990A</b>		7355	
Gen. ....	7540169		6834
P.T.O. ....	7540165		
<b>148-910A</b>			
Belt: W/59" Belt O.C. ....	7540218		6959
P.T.O. ....	7540214		6850
Transaxle .....	7540211		6946
<b>148-912A</b>			
P.T.O. ....	7540214		6850
Transaxle .....	7540212		6945
Variable Speed .....	7540210		6960
<b>148-916A</b>			
Belt: W/59" Belt O.C. ....	7540218		6959
P.T.O. ....	7540214		6850
Transaxle .....	7540211		6946
<b>148-918A</b>			
P.T.O. ....	7540214		6850
Transaxle .....	7540212		6945
Variable Speed .....	7540210		6960
<b>148-990A</b>		7355	
Gen. ....	7540169		6834
P.T.O. ....	7540165		
<b>2446 19"</b>			
Blade .....	BA50		6850
Drive; W/2-Speed Drive .....	T249		6849
<b>2447A</b>			
Blade .....	754138	3500	6950
Drive .....	754164	2630	6863
<b>2464</b>			
Drive .....	754164	2630	6863
<b>2501; 2502; 2503</b>			
Blade .....	20717		6856
Drive .....	20716		6837
<b>2503A</b>			
Blade .....	20556		6848
Cross Drive .....	20555		6841
Drive .....	20716		6837
<b>2513</b>			
Blade .....	20717		6856
Drive .....	20716		6837
<b>2514A</b>			
Blade .....	754127		6966
Drive .....	754166	3620	6962
<b>2523</b>			
Blade .....	20717		6856
Drive .....	20716		6837
<b>2533A; 2534</b>			
Blade .....	20556		6848
Cross Drive .....	20555		6841
Drive .....	20716		6837
<b>2537</b>			
Blade .....	754178	3820	6982
Drive .....	754185		6849

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GAMBLE SKOGMO - Continued</b>			
<b>2591A</b>			
Blade .....	754127		6966
Drive .....	754166	3620	6962
<b>2622</b>			
Blade .....	39456	3690	
Drive .....	39454		6463BR
<b>2633</b>			
Drive .....	39454		6463BR
<b>3023; 3063</b>			
Blade .....	20556		6848
Cross Drive .....	20555		6841
Drive .....	20716		6837
<b>3661; 3666; 3667</b>			
Blade .....	21649		6449BR
Cross Drive .....			6846
Drive .....	21615		6895
<b>5690</b>			
Blade - Left .....	61TR83	2310	6831
Blade - Right .....	61D35	2300	6830
Drive .....	61TR83	2310	6831
Gen. ....	61TR304	7320	
<b>5971; 5972; 5973</b>			
Blade .....	60R20	2330	6833
Eng. To J.S. ....	61TR183		6952
<b>9202; 9204; 9205</b>			
Trans. ....	754124		6857
<b>52760000; 52770000</b>			
Blade .....	41505		6835
Drive .....	30998		6842
<b>52810300</b>			
Blade .....	42111		6630BR
Drive .....	39455		6863
<b>52820200</b>			
Blade .....	39456	3690	
Drive .....	39454		6463BR
<b>52830300</b>			
Blade .....	42111		6630BR
Drive .....	39455		6863
<b>52850100; 52850200</b>			
Blade .....	39456	3690	
Drive .....	39454		6463BR
<b>52850500</b>			
Blade .....	42111		6630BR
Drive .....	39454		6463BR
<b>52882300</b>			
Blade .....	48044		6454BR
Drive .....	39454		6463BR
<b>52891700; 52891900; 52892600</b>			
Blade .....	47390		6871
Drive .....			6856
<b>52930000</b>			
Blade .....	42881		6971
Drive .....	42858	2390	
<b>C26-73</b>			
Blade .....	28819		6831
<b>FS22-750-0A</b>			
Deck; W/Optional 44" Deck .....	7540230		6755BR
Drive .....	7540245		6859
Transaxle .....	7540255		6837
<b>FS42-7025-2A</b>			
Deck .....	7540230		6755BR
Drive .....	7540245		6859
Transaxle .....	7540244		6840
<b>H1054; H1056; H1057; H1078</b>			
Blade .....	28819		6831

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GAMBLE SKOGMO - Continued</b>			
LM2-2551B; LM2-2621B			
Blade .....	42111		6630BR
Drive .....	39454		6463BR
LM2-2622A			
Blade .....			6971
Drive .....	39454		6463BR
LM22-2448-1A; LM22-2448-1C		3500	
Blade .....	7540138		6950
Drive .....	7540198		6451BR
LM22-2464B			
Blade .....	7540167		6964
Drive .....	7540198		6451BR
LM22-2513A			
Blade .....	754151		6967
Drive .....	754127		6966
LM22-2525A; LM22-2525R; LM22-2537A			
Drive .....	754127		6966
LM22-2538-9A; LM22-2538-9B			
Deck .....	7540198		6451BR
Drive .....	7540207		6842
LM22-2592A; LM22-2600A; LM22-2600E			
Drive .....	754127		6966
LM22-2602-3A; LM22-2603-1A; LM22-2604-9A		3500	
Blade .....	7540151		6967
Drive .....	7540138		6950
Trans. ....	7540136		6931
LM22-2652-8A			
Blade .....	7540195		6854
Drive .....	7540198		6451BR
LM22-25124A; LM22-26015A		3500	
Blade .....	7540151		6967
Drive .....	7540138		6950
Trans. ....	7540136		6931
LM22-26304A			
Blade .....	7540145		6488BR
Drive .....	7540173		6937
Trans. ....	7540191		6865
LM22-26510B; LM22-26510C			
Blade .....	7540195		6854
Drive .....	7540198		6451BR
LM40-2446-5E; LM40-2446A; LM40-2446B; LM40-24465C; LM40-24465D		2250	
Belt; W/25" Belt O.C. ....	T223		6825
Belt; W/49" Belt O.C. ....	T249		6849
Blade .....	BA50		6850
Drive .....			6850
LM43-2436A; LM43-2436B; LM43-2437; LM43-2437-4C; LM43-2437-4E; LM43-2437A			
Blade .....	20717		6856
Drive .....	20716		6837
LM43-2527A			
Blade .....	21649		6449BR
Cross Drive .....			6846
Drive .....	21614		6885
LM43-2530A; LM43-2533A			
Blade .....	20556		6848
Cross Drive .....	20555		6841
Drive .....	20716		6837
LM43-2534-8C			
Drive .....	20716		6837
LM43-2534A			
Blade .....	20556		6848
Cross Drive .....	20555		6841
Drive .....	20716		6837
LM43-2616A			
Blade .....	21649		6449BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GAMBLE SKOGMO - Continued</b>			
LM43-2616A - Continued			
Cross Drive .....			6846
Drive .....	21614		6885
LM43-2631-2A; LM43-2632-OB			
Blade .....	21649		6449BR
Cross Drive .....			6846
Drive .....	21615		6895
T1034; T1036; T1038			
Blade .....	28819		6831
<b>GENERAL ELECTRIC</b>			
E8; E10			
Belt; W/44" Belt O.C. ....	211A3226P11		6844
E12			
Trans. ....	211A3226P5		3VX355
E12M			
Belt; W/40" Belt O.C. ....	211A3226P10		3VX400
E12S			
Trans. ....	211A3226P5		3VX355
E15; E20			
Trans. ....			3VX335
<b>GENERAL LEISURE</b>			
024G5			
Trans. ....	530050017		6829
024G5C			
Blade .....	530050002		6825
Trans. ....	530050001		6831
024G5E; 024G7			
Trans. ....	530050017		6829
024G7D; 024G7DE			
Blade .....	530050002		6825
Trans. ....	530050001		6831
024G7E; 024G7X; 024G7XE			
Trans. ....	530050017		6829
025G5C; 025G5D; 025G7D; 025G7DE			
Blade .....	530050002		6825
Trans. ....	530050001		6831
026G8; 026G8E			
Blade .....	530050002		6825
Trans. ....	530050021		6829
026GRE5; 026GRE5D			
Blade; W/26" Blade .....	530050018		6855
Blade; W/36" Blade .....	530050023		6870
Trans. ....	530050015		6835
032G8; 032G8E			
Blade - Left .....	530050017		6829
Blade - Right .....	530050026		6828
Trans. ....	530050017		6829
032G8P; 032G8PE; 032G8PEL			
Blade .....	530050009		6857
Deck .....	530050008		6952
Trans. ....	530050003		6851
032T8P; 032T8PE; 032T8PEL			
Blade .....	530050009		6857
Deck .....	530050008		6952
J.S. ....	530050012		6856
Trans. ....	530050013		6828
036GRE8; 036GRE8E			
Blade; W/26" Blade .....	530050018		6855
Blade; W/36" Blade .....	530050023		6870
Trans. ....	530050015		6835
036T8P; 036T8PE; 036T8PEL			
Blade .....	530050019		6876
Deck .....	530050022		6843
J.S. ....	530050012		6856
Trans. ....	530050013		6828



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GENERAL LEISURE - Continued</b>			
<b>728T5P; 732F5P; 732F7P; 742T7P; 828T5C; 832T7P; 832T7PE; 832T7PEL; 832TPS</b>			
Blade; W/28" Blade			6854
Blade; W/32" Blade	Z168Z1		6857
Deck	Z167Z1		6952
J.S.	Z170Z1		6856
J.S. To Trans	Z171Z1		6828
Trans.	106911		6847
<b>924G5; 924G5C; 924G5D; 924G7; 925G5C; 925G5D; 925G7</b>			
Blade	530050002		6825
Trans.	530050001		6831
<b>932G7P; 932G7PE; 932G7PEL</b>			
Blade	530050009		6857
Deck	530050008		6952
Trans.	530050003		6851
<b>932T7P; 932T7PE; 932T7PEL</b>			
Blade; W/28" Blade			6854
Blade; W/32" Blade	Z168Z1		6857
Deck	Z167Z1		6952
J.S.	Z170Z1		6856
J.S. To Trans	Z171Z1		6828
Trans.	106911		6847
<b>ALC1001; ALC1010</b>			
Trans.	530050017		6829
<b>ALE1016</b>			
Blade; W/32" Blade	530050009		6857
Blade; W/36" Blade	530050028		6864
J.S.	530050012		6856
Trans.	530050013		6828
<b>B1C1002; C1X02</b>			
Trans.	530050017		6829
<b>C1X05</b>			
Blade	530050002		6825
Trans.	530050001		6831
<b>C1X13</b>			
Blade	530050002		6825
Trans.	530050021		6829
<b>C1X20; C1X21</b>			
Blade	530050002		6825
Trans.	530050001		6831
<b>C23X0; C23X1</b>			
Trans.	530050017		6829
<b>C23X2; C23X3</b>			
Blade	530050002		6825
Trans.	530050001		6831
<b>C23X4</b>			
Blade - Left	530050017		6829
Blade - Right	530050026		6828
Trans.	530050017		6829
<b>C1001; C1002; C1003</b>			
Trans.	530050017		6829
<b>C1005</b>			
Blade	530050002		6825
Trans.	530050001		6831
<b>C1007; C1008; C1009; C1010</b>			
Blade	530050002		6825
Trans.	530050021		6829
<b>C1011; C1012</b>			
Blade - Left	530050017		6829
Blade - Right	530050026		6828
Trans.	530050017		6829
<b>C1013</b>			
Blade	530050002		6825
Trans.	530050021		6829
<b>C1015</b>			
Trans.	530050017		6829

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GENERAL LEISURE - Continued</b>			
<b>C1017</b>			
Blade	530050002		6825
Trans.	530050021		6829
<b>C1018</b>			
Trans.	530050017		6829
<b>C1019</b>			
Blade	530050002		6825
Trans.	530050021		6829
<b>C1020; C1021</b>			
Trans.	530050017		6829
<b>C1022</b>			
Blade	530050002		6825
Trans.	530050021		6829
<b>D1001; D1002; D1003; D1005</b>			
Blade; W/26" Blade	530050018		6855
Blade; W/36" Blade	530050023		6870
Trans.	530050015		6835
<b>D2350; D2351; D2352</b>			
Blade; W/26" Blade	530050018		6855
Blade; W/32" Blade	530050037		6853
Blade; W/36" Blade	530050041		6868
Deck	530050038		6862
Trans.	530050015		6835
<b>E1X01; E1X02</b>			
Blade	530050009		6857
Deck	530050008		6952
Trans.	530050003		6851
<b>E1X11; E1X12</b>			
Blade	530050009		6857
Deck	530050008		6952
J.S.	530050012		6856
Trans.	530050013		6828
<b>E1X30; E1X31</b>			
Blade	530050009		6857
Deck	530050008		6952
Trans.	530050003		6851
<b>E1X32; E1X35</b>			
Blade	530050009		6857
Deck	530050008		6952
J.S.	530050012		6856
Trans.	530050013		6828
<b>E1001; E1002; E1004; E1006</b>			
Blade; W/32" Blade	530050009		6857
Blade; W/36" Blade	530050028		6864
Trans.	530050003		6851
<b>E1011; E1012</b>			
Blade; W/32" Blade	530050009		6857
Blade; W/36" Blade	530050028		6864
Deck	530050008		6952
J.S.	530050012		6856
Trans.	530050013		6828
<b>E1014; E1015; E1016; E1018; E1019</b>			
Blade; W/32" Blade	530050009		6857
Blade; W/36" Blade	530050028		6864
J.S.	530050012		6856
Trans.	530050013		6828
<b>E1020</b>			
Blade	530050019		6876
Deck	530050022		6843
J.S.	530050012		6856
Trans.	530050013		6828
<b>E1025</b>			
Blade; W/32" Blade	530050009		6857
Blade; W/36" Blade	530050028		6864
J.S.	530050012		6856
Trans.	530050013		6828
<b>E1026; E1027</b>			
Blade	530050009		6857
Deck	530050008		6952
Trans.	530050003		6851

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GENERAL LEISURE - Continued</b>			
<b>E1029; E1033; E1034</b>			
Blade; W/32" Blade .....	530050009		6857
Blade; W/36" Blade .....	530050028		6864
J.S. ....	530050012		6856
Trans. ....	530050013		6828
<b>E3401; E3402; E3405</b>			
Blade .....	530050028		6864
J.S. ....	530050053		6857
Trans. ....	530050049		6827
Variable Speed .....	530050051		6841
<b>G1E1000</b>			
Blade .....	530050009		6857
Deck .....	530050008		6952
J.S. ....	530050012		6856
Trans. ....	530050013		6828
<b>V1C1002E; V166</b>			
Trans. ....	530050017		6829
<b>V167</b>			
Blade .....	530050002		6825
Trans. ....	530050021		6829
<b>V169</b>			
Blade .....	530050009		6857
Deck .....	530050008		6952
Trans. ....	530050003		6851
<b>V170</b>			
Blade .....	530050009		6857
Deck .....	530050008		6952
J.S. ....	530050012		6856
Trans. ....	530050013		6828
<b>GIANT VAC</b>			
<b>1648</b>			
Belt; W/52" Belt O.C. ....			6952
Belt; W/81" Belt O.C. ....			6981
<b>Giant Mow M-1136; Giant Mow M-1146; Giant Mow M-1148</b>			
Spindle .....			6967
Trans. ....			3V315
<b>Giant Mow M-1661; Giant Mow M-1661B</b>			
Spindle .....	3670		6967
Trans. ....			3V315
<b>GILSON</b>			
<b>11/38</b>			
Eng. To Deck .....	GB237736		6886
<b>12/381C</b>			
Eng. To Deck .....			6885
<b>40-720-01; 40-721-01; 40-722-01; 40-723-01; 40-728-03; 40-729-03</b>			
Drive .....	11144		6835
Trans. ....			6852
<b>40-915-15; 40-939-01; 40-940-01; 40-941-01; 40-952-15; 40-953-15; 44-1897-849</b>			
Drive .....			6852
<b>44-2834</b>			
Traction .....	216594		6378
<b>60-895; 60-896; 60-965; 60-966</b>			
Trans. ....	4638		6830
<b>722; 723; 723L; 750; 750L</b>			
Drive .....	11144		6835
Trans. ....			6852
<b>754; 755</b>			
Drive .....	16348		6838
Trans. ....			6852
<b>768; 772; 773; 775; 776</b>			
Eng. To Deck .....	14159		6840
Traction; W/51" Belt O.C. ....	14168		6851
Traction; W/65" Belt O.C. ....	14167		6865

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
<b>778; 779; 780</b>			
Drive .....			6852
<b>804; 805</b>			
Blade .....			6854
<b>806</b>			
Blade .....	14365		A49
<b>807; 810</b>			
Eng. To Blade .....	13560		6859
<b>811; 815</b>			
Blade .....			6854
<b>816</b>			
Blade .....	14365		A49
<b>817; 818</b>			
Eng. To Blade .....	13560		6859
<b>849</b>			
Drive .....	16348		6838
Trans. ....			6852
<b>850; 851; 852; 859; 860; 861; 862; 863; 866</b>			
Blade .....	10923		6830
Traction .....	10897		6851
<b>867</b>			
P.T.O. ....	11943		6935
<b>868</b>			
Blade .....			6854
<b>870; 872; 873; 874; 875</b>			
Blade .....	10923		6830
Traction .....	10897		6851
<b>3387</b>			
Eng. To Deck .....			6885
<b>12023; 31190A; 33130C; 33144D; 33145D; 33149B; 33153B; 33154C; 33155C; 33156B</b>			
Hyd. Lift .....	12023		6721
P.T.O. ....	11943	3350	6935
Trans. ....	11901		6836
<b>33157B; 33160C; 33162B; 33180A; 33181A; 33182A; 33183A; 33184A; 33185A; 33186A</b>			
Hyd. Lift .....	12023		6721
P.T.O. ....	11943	3350	6935
Trans. ....	11901		6836
<b>33187A; 33188A; 33189A</b>			
Hyd. Lift .....	12023		6721
P.T.O. ....	11943	3350	6935
Trans. ....	11901		6836
<b>52012</b>			
Blade .....			6854
<b>52013</b>			
Blade .....	14365		A49
<b>52014; 52015</b>			
Eng. To Blade .....	17518		6960
<b>52016</b>			
Blade .....	14365		A49
<b>52017</b>			
Blade .....			6854
<b>52018</b>			
Eng. To Blade .....	17518		6960
<b>52019; 52020; 52029</b>			
Blade .....			6854
<b>52031</b>			
Blade .....	14365		A49
<b>52032; 52033</b>			
Deck .....	23472		3V560
<b>52034</b>			
Blade .....	14365		A49



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
52037 Drive .....	27666		A33
52038; 52038A Blade .....	14365		A49
52039; 52040 Deck .....	23472		3V560
52051; 52052 Belt; W/42" Deck .....	11793		6989
52080 Blade .....	213676		6885
52081A; 52082A Eng. To Deck .....	210692		6896
52084 Traction .....	216594		6378
53000; 53001 Drive .....	11144		6835
Trans. ....			6852
53002; 53003; 53004; 53005 P.T.O. ....	11943		6935
53007 P.T.O. ....	11943		6935
Trans. ....	11901		6836
53008 Drive .....	11144		6835
Trans. ....			6852
53009 P.T.O. ....	11943		6935
Trans. ....	11901		6836
53010 P.T.O. ....	11943		6935
53011 Drive .....			6852
53012 Drive .....	11144		6835
Trans. ....			6852
53013; 53014; 53016 P.T.O. ....	11943		6935
53018; 53019 Drive .....	11901		6836
Hyd. Lift .....	12023		6721
P.T.O. ....	11943		6935
Trans. ....	11901		6836
53020 P.T.O. ....	11943		6935
53021 Drive .....	11901		6836
Hyd. Lift .....	12023		6721
P.T.O. ....	11943		6935
Trans. ....	11901		6836
53022; 53023; 53024; 53025 P.T.O. ....	11943		6935
53026 Drive .....	11901		6836
Hyd. Lift .....	12023		6721
P.T.O. ....	11943		6935
Trans. ....	11901		6836
53027; 53028 P.T.O. ....	11943		6935
53029 Drive .....	11901		6836
Hyd. Lift .....	12023		6721
P.T.O. ....	11943		6935
Trans. ....	11901		6836
53030; 53031 P.T.O. ....	11943		6935

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
53030; 53031 – Continued Trans. ....	11901		6836
53032 Drive .....	11901		6836
Hyd. Lift .....	12023		6721
P.T.O. ....	11943		6935
Trans. ....	11901		6836
53033; 53034 Drive .....	18263		6844
53038 Drive .....	18263		6844
Eng. To J.S. ....	36806		6953
Mower To Deck .....	11793		6989
53039 Drive .....	18263		6844
53040 Drive .....	18263		6844
Eng. To J.S. ....	36806		6953
Mower To Deck .....	11793		6989
53041 Drive .....	200804		6874
Trans. ....	36770		6835
53042; 53043 Trans. ....	11901		6836
15265077 Blade .....		3690	6969
Trans. ....			6885
15265101 Blade .....			6930
Trans. ....			6852
YT12E Eng. To Deck .....			6866
<b>GOODALL</b>			
Auto – 30" Belt .....	W00630	1570	6757
Brookwood – 36" Rider Blade .....	W00693	3590	6959
Eng. To Blade .....	W00695	3310	6931
<b>GRAINGER, W. W.</b>			
3Z457A; 3Z457B; 3Z457C Blade .....	7540167		6964
Trans. ....	7540198		6451BR
3Z458 Blade .....	7540151		6967
Deck .....	7540138	3500	6950
Trans. ....	7540136		6931
3Z459 Blade .....	7540145		6488BR
Trans. ....	7540127		6966
3Z459A; 3Z459B; 3Z459C; 3Z459D Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
3Z459E; 3Z459G; 3Z459H; 3Z459L Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
3Z460A Blade .....	7540178	3820	6982
Trans. ....	7540200		6848
3Z480; 3Z480A Blade .....	7540151		6967
Deck .....	7540138	3500	6950
Trans. ....	7540136		6931
3Z480B Blade .....	7540151		6967

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAINGER, W. W. - Continued</b>			
<b>3Z480B - Continued</b>			
Drive .....	7540136		6931
<b>3Z480C; 3Z480D</b>		3500	
Blade .....	7540151		6967
Deck .....	7540138		6950
Trans. ....	7540136		6931
<b>3Z481</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>3Z497B</b>		3370	
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173		6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>3Z590; 3Z590A; 3Z590B</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>3Z641; 3Z641A</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>3Z678; 3Z678A; 3Z678E</b>			
P.T.O.; W/41" Belt O.C. ....	7540234		6841
P.T.O.; W/63" Belt O.C. ....	7540227		6963
Trans. ....	7540212		6945
<b>3Z715; 3Z715D</b>			
Deck .....	7540230		6755BR
J.S. ....	7540245		6859
Transaxle .....	7540244		6840
<b>3Z716</b>		3500	
Blade .....	7540151		6967
Deck .....	7540138		6950
Trans. ....	7540136		6931
<b>3Z807D</b>			
Eng. To Deck .....	7540264		6639BR
Primary Variator .....	7540241		6494BR
Secondary Variator .....	7540240		6511BR
<b>147-862</b>			
Deck .....	7540177		6832
Traction .....	7540245		6859
<b>GRASSHOPPER</b>			
<b>120K-48; 124-48</b>			
Deck Drive .....	382084		6785BR
<b>124-52</b>			
Deck Drive .....	382093		6567BR
<b>220-48</b>			
Hydro. Pump .....	382034		6406BR
<b>223-52</b>			
Deck Drive .....	382082		6574BR
Hydro. Pump .....	382034		6406BR
Mule Drive .....	382085		6786BR
<b>223-61</b>			
Deck Drive .....	382085		6786BR
Hydro. Drive .....	382034		6406BR
Mule Drive .....	382085		6786BR
<b>225-52</b>			
Blade Drive .....	382082		6574BR
Hydro. Drive .....	382034		6406BR
Mule Drive .....	382085		6786BR
<b>225-61</b>			
Blade Drive .....	382085		6786BR
Hydro. Drive .....	382034		6406BR
Mule Drive .....	382085		6786BR
<b>225-72</b>			
Blade Drive .....	382098		6598BR
Hydro. Drive .....	382034		6406BR
Mule Drive .....	382095		6767BR
<b>226V-52</b>			
Deck Drive .....	382111		6746BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRASSHOPPER - Continued</b>			
<b>226V-52 - Continued</b>			
Hydro. Drive .....	382025		BX52
<b>226V-61</b>			
Hydro. Drive .....	382025		BX52
<b>227-52</b>			
Deck Drive .....	382082		6574BR
Hydro. Pump .....	382034		6406BR
Mule Drive .....	382085		6786BR
<b>227-61</b>			
Deck Drive .....	382085		6786BR
Hydro. Drive .....	382034		6406BR
Mule Drive .....	382085		6786BR
<b>227-72</b>			
Deck Drive .....	382098		6598BR
Hydro. Drive .....	382034		6406BR
Mule Drive .....	382095		6767BR
<b>321D</b>			
Blade Drive; W/52" Deck .....	382082		6574BR
Mule Drive .....	382095		6767BR
<b>322D</b>			
Blade Drive; W/61" Deck .....	382085		6786BR
Blade Drive; W/72" Deck .....	382098		6598BR
Mule Drive; W/61" Deck .....	382110		6745BR
<b>325</b>			
Blade Drive; W/52" Deck .....	382082		6574BR
Blade Drive; W/61" Deck .....	382085		6786BR
Mule Drive; W/52", 61" Deck .....	382095		6767BR
Mule Drive; W/72" Deck .....	382098		6598BR
<b>325D</b>			
Deck Drive; W/52" Deck .....	382082		6574BR
Deck Drive; W/61" Deck .....	382085		6786BR
Deck Drive; W/72" Deck .....	382098		6598BR
Mule Drive; W/52", 61" Deck .....	382111		6746BR
<b>327</b>			
Deck Drive; W/52" Deck .....	382082		6574BR
Deck Drive; W/61" Deck .....	382085		6786BR
Deck Drive; W/72" Deck .....	382098		6598BR
Mule Drive .....	382093		6567BR
<b>329</b>			
Deck Drive; W/52" Deck .....	382082		6574BR
Deck Drive; W/61" Deck .....	382085		6786BR
Deck Drive; W/72" Deck .....	382098		6598BR
Mule Drive; W/52", 61" Deck .....	382111		6746BR
<b>329B</b>			
Deck Drive; W/52" Deck .....	382082		6574BR
Deck Drive; W/61" Deck .....	382085		6786BR
Deck Drive; W/72" Deck .....	382098		6598BR
Mule Drive; W/52", 61" Deck .....	382093		6567BR
<b>335</b>			
Deck Drive; W/61" Deck .....	382085		6786BR
Deck Drive; W/72" Deck .....	382098		6598BR
Mule Drive; W/61" Deck .....	382093		6567BR
<b>428D</b>			
Blade Drive; W/61" Deck .....	382085		6786BR
Blade Drive; W/72" Deck .....	382098		6598BR
Mule Drive; W/61" Deck .....	382097		6983BR
Mule Drive; W/72" Deck .....	382099		6760BR
<b>430D</b>			
Deck Drive; W/61" Deck .....	382085		6786BR
Deck Drive; W/72" Deck .....	382098		6598BR
Mule Drive; W/61" Deck .....	382097		6983BR
Mule Drive; W/72" Deck .....	382099		6760BR
<b>432</b>			
Deck Drive; W/61" Deck .....	382085		6786BR
Deck Drive; W/72" Deck .....	382098		6598BR
<b>614; 616</b>			
P.T.O. ....	381914		6528BR
<b>618</b>			
Deck Drive; W/52" Deck .....	382084		6785BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRASSHOPPER - Continued</b>			
<b>618 – Continued</b>			
P.T.O. ....	381914		6528BR
<b>620T</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
<b>718</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
P.T.O. ....	381914		6528BR
<b>718KH2</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
<b>721</b>			
Eng. To J.S. ....	381914		6528BR
Pump .....	381904		6834
<b>721D</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
P.T.O. ....	381914		6528BR
Pump Drive .....	381904		6834
<b>721D2</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
P.T.O. ....	381914		6528BR
Pump Drive .....	381540		6734
<b>721DH2</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
P.T.O. ....	381914		6528BR
<b>721DT</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
<b>722D; 722D2</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
P.T.O. ....	381914		6528BR
Pump Drive .....	381540		6734
<b>723KH2</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
P.T.O. ....	381914		6528BR
<b>723T</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
<b>725DT</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
<b>725K2</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
P.T.O. ....	381914		6528BR
<b>727K2</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
P.T.O. ....	381914		6528BR
<b>727T; 729BT</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
<b>729G2</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRASSHOPPER - Continued</b>			
<b>729G2 – Continued</b>			
P.T.O. ....	381914		6528BR
<b>729T; 735BT</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
<b>928D</b>			
Fan .....		7375	
P.T.O. ....	381914		6528BR
Pump .....	381904		6834
<b>928D2</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
P.T.O. ....	381914		6528BR
Pump Drive .....	381540		6734
<b>930D; 932</b>			
Deck Drive; W/52" Deck .....	382084		6785BR
Deck Drive; W/61" Deck .....	382090		6906BR
Deck Drive; W/72" Deck .....	382099		6760BR
<b>1200; 1210</b>			
P.T.O. ....	381100		6929
<b>1600; 1610; 1620; 1820</b>			
P.T.O. ....	382000		6933
<b>1822</b>			
P.T.O.; W/Diesel Eng. ....	381914		AX34
P.T.O.; W/Gas Eng. ....	382000		6933
<b>BT1600</b>			
P.T.O. ....	382000		6933
<b>GRAVELY</b>			
<b>18H</b>			
Eng. To P.T.O. ....	72111		6834
<b>408</b>			
Eng. To P.T.O. ....	15242P1		6829
P.T.O. To Mower .....	15355		6838
Trans. ....	15243P1		6463BR
<b>424</b>			
Deck Drive .....	14673P1		68117
Gen. ....	10860		6735
<b>830; 830E; 1130E</b>			
Blade .....	26149		6868
Transaxle .....	26137		6731
<b>1132; 1138</b>			
Deck; W/38" Deck .....	35955		6853
Eng. To Deck .....	36004		6847
Eng. To J.S. ....	36232		6871
J.S. To Trans. ....	36233		6830
<b>1934FX</b>			
Deck Drive .....	00201010		6815BR
<b>1948FL; 1948FX</b>			
Hydro. Drive .....	07200118		6559BR
<b>2352FL; 2352FX</b>			
Deck Drive .....	07200120		6492BR
Hydro. Drive .....	07200118		6559BR
<b>20060; 21297; 31220</b>			
Blade .....	72266		6486BR
<b>32238; 32239; 32240</b>			
Blade .....	32322		6872
Transaxle .....	32330		3V450
<b>34129; 34130; 34156</b>			
Blade .....	32322		6872
<b>34427; 35000; 37837; 38070; 38681; 38682; 38684; 38685; 38994; 39000</b>			
Blade .....	72266		6486BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAVELY - Continued</b>			
40202; 40340; 41980; 44140; 45161; 45533; 45706; 45742; 45764; 45810			
Blade .....	72266		6486BR
885006; 885007; 885039; 887017; 887020; 887025; 887028; 887029; 889017; 889026			
Blade .....	72266		6486BR
889029			
Blade .....	72266		6486BR
988016; 988035; 988037; 988038			
Wheel Drive .....	041599		6549BR
988039			
Blade .....	041599		6549BR
988040; 988041; 988042			
Wheel Drive .....	041599		6549BR
988043			
Blade .....	041599		6549BR
988044; 988045; 988046; 988047; 988048; 988051; 988052; 988053; 988054; 988055			
Wheel Drive .....	041599		6549BR
988056; 988057			
Wheel Drive .....	041599		6549BR
989005; 989016; 989019; 989024; 989025; 989028; 989029; 989034			
Blade .....	72266		6486BR
<b>Commercial 8</b>			
Fan .....	5163P1		6831
<b>Commercial 10</b>			
Gen. ....	10860P1		6735
Starter/Gen. ....	10860		6735
<b>Commercial 10A; Commercial 12</b>			
Fan .....	5163P1		6831
<b>Compact-Pro 34</b>			
Deck Drive .....	07200011		7041BR
Hydro. Drive .....	07200010		6498BR
<b>Compact-Pro 44</b>			
Blade Drive .....	07200035		6654BR
Eng. To Deck .....	07200026		6788BR
Hydro. Drive .....	07211500		6448BR
<b>GMT-90-IPL; GMT-9000; GMT-9000-IPL</b>			
Fan .....	21692		6725
<b>L Series</b>			
Fan .....	5163P1		6831
Gov. ....			6722
Main Drive .....	5163		6831
<b>PM 144M</b>			
Blade - Right .....	07200035		6654BR
Eng. To Deck .....	07200024		7062BR
Hydro. Drive .....	07218000		6552BR
<b>PM 144M XDZ</b>			
Blade - Right .....	07200035		6654BR
Eng. To Deck .....	07200024		7062BR
Hydro. Drive .....	07243300		6674BR
<b>PM 148M</b>			
Blade - Right .....	07200035		6654BR
Eng. To Deck .....	07200025		7121BR
Hydro. Drive .....	07218000		6552BR
<b>PM 148M XDZ</b>			
Blade - Right .....	07200035		6654BR
Eng. To Deck .....	07200025		7121BR
Hydro. Drive .....	07243300		6674BR
<b>PM 152M</b>			
Blade - Right .....	07200036		6790BR
Eng. To Deck .....	07200026		6788BR
Hydro. Drive .....	07218000		6552BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAVELY - Continued</b>			
<b>PM 152M XDZ</b>			
Blade - Right .....	07200036		6790BR
Eng. To Deck .....	07200026		6788BR
Hydro. Drive .....	07243300		6674BR
<b>PM 160M</b>			
Blade - Right .....	07200038		6791BR
Eng. To Deck .....	07200028		6789BR
Hydro. Drive .....	07218000		6552BR
<b>PM 252M XDZ</b>			
Blade - Right .....	07200036		6790BR
Eng. To Deck .....	07200026		6788BR
Hydro. Drive .....	07242000		7128BR
<b>PM 260H LP XDZ</b>			
Blade - Right .....	07200038		6791BR
Eng. To Deck .....	07200028		6789BR
Hydro. Drive .....	07242000		7128BR
<b>PM 260H XDZ</b>			
Blade - Right .....	07200038		6791BR
Eng. To Deck; W/Kohler Eng. ....	07200028		6789BR
Hydro. Drive; W/Kohler Eng. ....	07242000		7128BR
<b>PM 260M XDZ</b>			
Blade - Right .....	07200038		6791BR
Eng. To Deck .....	07200028		6789BR
Hydro. Drive .....	07242000		7128BR
<b>PM 266H XDZ</b>			
Blade - Right .....	07200435		7056BR
Hydro. Drive .....	07242000		7128BR
<b>PM 272H XDZ</b>			
Blade - Right .....	07200039		7114BR
Hydro. Drive; W/Kawasaki Eng. ....	07242000		7128BR
<b>PM 320HD</b>			
Blade - Right; W/60" Deck .....	07200038		6791BR
Eng. To Deck; W/72" Deck .....	07237800		6488BR
Hydro. Drive .....	07224300		6735BR
<b>PM Rapid XZ</b>			
Blade - Right; W/52" Deck .....	07200036		6790BR
Blade - Right; W/60" Deck .....	07200038		6791BR
Blade - Right; W/72" Deck .....	07200039		7114BR
Eng. To Deck; W/52" Deck .....	07200039		7114BR
Hydro. Drive .....	07224300		6735BR
<b>Pro-Master 260H</b>			
Blade Drive .....	07200038		6791BR
Eng. To Deck .....	07200028		6789BR
Hydro. Drive .....	07242000		7128BR
<b>Pro-Master 260H RD</b>			
Blade Drive .....	07200613		7094BR
Eng. To Deck .....	07200611		6596BR
Hydro. Drive .....	07242000		7128BR
<b>Pro-Ride 254</b>			
Deck Drive .....	00181036		6665BR
Eng. To Deck .....	00181715		6665BR
Hydro. Drive .....	00181727		6943BR
<b>Pro-Ride 260</b>			
Deck Drive .....	00112616		6589BR
Eng. To Deck .....	00181715		6665BR
Hydro. Drive .....	00181727		6943BR
<b>Pro-Ride 266</b>			
Deck Drive .....	00181711		6946BR
Eng. To Deck .....	00181715		6665BR
Hydro. Drive .....	00181727		6943BR
<b>Pro-Stance34FX</b>			
Deck Drive .....	00201010		6815BR
Hydro. Drive .....	07200118		6559BR
<b>Pro-Stance48</b>			
Hydro. Drive .....	07226400		7045BR
<b>Pro-Stance48FL</b>			
Deck Drive .....	TCU18847		6949BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAVELY - Continued</b>			
<b>Pro-Stance48FX</b>			
Deck Drive .....	TCU18847		6949BR
Hydro. Drive .....	GDU10025		6559BR
<b>Pro-Stance52</b>			
Deck Drive .....	07200712		6845BR
Hydro. Drive .....	07226400		7045BR
<b>Pro-Stance52FL</b>			
Deck Drive .....	TCU18848		6492BR
<b>Pro-Stance52FX</b>			
Deck Drive .....	TCU18848		6492BR
Hydro. Drive .....	GDU10025		6559BR
<b>Pro-Stance60</b>			
Deck Drive .....	07200713		6787BR
Hydro. Drive .....	07226400		7045BR
<b>Pro-Stance61</b>			
Deck Drive .....	07200632		6692BR
Hydro. Drive .....	07226400		7045BR
<b>Pro-Turn 48</b>			
Blade Drive .....	07200035		6654BR
Eng. To Deck .....	07200024		7062BR
Hydro. Drive .....	07226400		7045BR
<b>Pro-Turn 52</b>			
Blade Drive .....	07200036		6790BR
Eng. To Deck .....	07200509		7063BR
Hydro. Drive .....	07226400		7045BR
<b>Pro-Turn 60</b>			
Blade Drive .....	07200038		6791BR
Eng. To Deck .....	07200510		7064BR
Hydro. Drive .....	07226400		7045BR
<b>Pro-Turn 148</b>			
Blade - Right .....	07200035		6654BR
Eng. To Deck .....	07200024		7062BR
Hydro. Drive .....	07226400		7045BR
<b>Pro-Turn 152</b>			
Blade - Right .....	07200036		6790BR
Eng. To Deck .....	07200509		7063BR
Hydro. Drive .....	07226400		7045BR
<b>Pro-Turn 160</b>			
Blade - Right .....	07200038		6791BR
Eng. To Deck .....	07200510		7064BR
Hydro. Drive .....	07226400		7045BR
<b>Pro-Turn 252</b>			
Blade - Right .....	07200036		6790BR
Eng. To Deck; 2014 & Older .....	07200509		7063BR
Eng. To Deck; 2015 & Newer .....	07200729		6589BR
Hydro. Drive .....	07200515		6846BR
<b>Pro-Turn 260</b>			
Blade - Right .....	07200038		6791BR
Eng. To Deck; 2014 & Older .....	07200510		7064BR
Eng. To Deck; 2015 & Newer .....	07234600		6845BR
Hydro. Drive .....	07200515		6846BR
<b>Pro-Turn 266</b>			
Blade - Right .....	07200435		7056BR
Hydro. Drive .....	07200515		6846BR
<b>Pro-Turn 272</b>			
Blade Drive .....	07200039		7114BR
Eng. To Deck; 2014 & Older .....	07200616		7065BR
Eng. To Deck; 2015 & Newer .....	07200731		7069BR
Hydro. Drive .....	07200515		6846BR
<b>Pro-Turn 452</b>			
Blade Drive .....	07200036		6790BR
Eng. To Deck; 2014 & Older .....	07200509		7063BR
Eng. To Deck; 2015 & Newer .....	07200729		6589BR
Hydro. Drive .....	07200515		6846BR
<b>Pro-Turn 460</b>			
Blade Drive .....	07200038		6791BR
Eng. To Deck; 2014 & Older .....	07200510		7064BR
Eng. To Deck; 2015 & Newer .....	07234600		6845BR
Hydro. Drive .....	07200515		6846BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAVELY - Continued</b>			
<b>Pro-Turn 472</b>			
Blade Drive .....	07200039		7114BR
Eng. To Deck; 2014 & Older .....	07200616		7065BR
Eng. To Deck; 2015 & Newer .....	07200731		7069BR
Hydro. Drive .....	07200515		6846BR
<b>ZT X 42</b>			
Deck Drive .....	07200523		7089BR
Transaxle; Ser. No. 015999 & Before .....	07200718		7073BR
Transaxle; Ser. No. 016000 & After .....	07200724		7074BR
<b>ZT X 52</b>			
Deck Drive .....	07200023		6708BR
Transaxle; Ser. No. 015999 & Before .....	07200718		7073BR
Transaxle; Ser. No. 016000 & After .....	07200724		7074BR
<b>ZT34</b>			
Deck Drive .....	07200116		6944BR
Hydro. Drive .....	07200010		6498BR
<b>ZT42</b>			
Deck Drive .....	07200523		7089BR
Hydro. Drive .....	07200010		6498BR
<b>ZT42XL</b>			
Deck Drive .....	07219600		6486BR
Hydro. Drive .....	07242200		6793BR
<b>ZT44HD</b>			
Blade Drive .....	07200035		6654BR
Eng. To Deck .....	07200026		6788BR
Hydro. Drive .....	07211500		6448BR
<b>ZT48HD</b>			
Blade Drive .....	07200035		6654BR
Eng. To Deck .....	07200025		7121BR
Hydro. Drive .....	07211500		6448BR
<b>ZT48XL</b>			
Deck Drive .....	07200436		6842BR
Hydro. Drive .....	07242200		6793BR
<b>ZT50</b>			
Deck Drive .....	07200524		6978BR
Hydro. Drive .....	07200010		6498BR
<b>ZT52HD</b>			
Blade Drive .....	07200036		6790BR
Eng. To Deck .....	07200026		6788BR
Hydro. Drive .....	07211500		6448BR
<b>ZT54XL</b>			
Deck Drive .....	07200023		6708BR
Hydro. Drive .....	07242200		6793BR
<b>ZT60HD</b>			
Blade Drive .....	07200038		6791BR
Eng. To Deck .....	07200028		6789BR
Hydro. Drive .....	07211500		6448BR
<b>ZT1534</b>			
Deck Drive .....	07200015		6776BR
Eng. To Deck .....	07229000		6896BR
<b>ZT1540</b>			
Deck Drive .....	07200002		6928BR
Eng. To Deck .....	07229000		6896BR
<b>ZT1640</b>			
Deck Drive; Ser. No. 025000 & Before ...	07200001		6662BR
Hydro. Drive .....	07241400		6943BR
<b>ZT1734</b>			
Deck Drive .....	07200116		6944BR
Eng. To Deck .....	07237900		6792BR
<b>ZT1734XL</b>			
Deck Drive .....	07200015		6776BR
Eng. To Deck .....	07237900		6792BR
<b>ZT1840</b>			
Deck Drive; Ser. No. 025000 & Before ...	07241800		6945BR
Deck Drive; Ser. No. 025001 & After .....	07219600		6486BR
Hydro. Drive .....	07241400		6943BR
<b>ZT1842XL</b>			
Deck Drive .....	07219600		6486BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAVELY - Continued</b>			
<b>ZT1842XL – Continued</b>			
Eng. To Deck .....	07242200		6793BR
<b>ZT2040</b>			
Deck Drive .....	07241800	6945BR	
Eng. To Deck .....	07237900	6792BR	
<b>ZT2042XL</b>			
Deck Drive .....	07219600	6486BR	
Hydro. ....	07242200	6793BR	
<b>ZT2044</b>			
Deck Drive; Ser. No. 025000 & Before ...	07241700	7100BR	
Hydro. Drive .....	07241400	6943BR	
<b>ZT2044XL</b>			
Deck Drive .....	07241600	6716BR	
Eng. To Deck .....	07200010	6498BR	
<b>ZT2250</b>			
Deck Drive .....	07200107	7054BR	
Eng. To Deck .....	07237900	6792BR	
<b>ZT2344HD</b>			
Deck Drive .....	07200035	6654BR	
Eng. To Deck .....	07200026	6788BR	
Hydro. Drive .....	07211500	6448BR	
<b>ZT2348</b>			
Deck Drive; Ser. No. 025000 & Before ...	07241500	6727BR	
Deck Drive; Ser. No. 025001 & After .....	07200022	6978BR	
Hydro. Drive .....	07241400	6943BR	
<b>ZT2348HD</b>			
Deck Drive .....	07200035	6654BR	
Eng. To Deck .....	07200025	7121BR	
Hydro. Drive .....	07211500	6448BR	
<b>ZT2348XL</b>			
Deck Drive .....	07241600	6716BR	
Eng. To Deck .....	07200010	6498BR	
<b>ZT2350</b>			
Deck Drive .....	07200107	7054BR	
Eng. To Deck .....	07237900	6792BR	
<b>ZT2448XL</b>			
Deck Drive .....	07200436	6842BR	
Eng. To Deck .....	07242200	6793BR	
<b>ZT2450</b>			
Deck Drive .....	07200107	7054BR	
Eng. To Deck .....	07237900	6792BR	
<b>ZT2548XL</b>			
Deck Drive .....	07200436	6842BR	
Hydro. ....	07242200	6793BR	
<b>ZT2550</b>			
Deck Drive .....	07200107	7054BR	
Eng. To Deck .....	07237900	6792BR	
<b>ZT2552</b>			
Deck Drive; Ser. No. 025000 & Before ...	07241600	6716BR	
Deck Drive; Ser. No. 025001 & After .....	07200023	6708BR	
Hydro. Drive .....	07241400	6943BR	
<b>ZT2552HD</b>			
Deck Drive .....	07200036	6790BR	
Eng. To Deck .....	07200026	6788BR	
Hydro. Drive .....	07211500	6448BR	
<b>ZT2554XL</b>			
Deck Drive .....	07200023	6708BR	
Eng. To Deck .....	07242200	6793BR	
<b>ZT2560HD; ZT2660HD; ZT2760HD</b>			
Deck Drive .....	07200038	6791BR	
Eng. To Deck .....	07200028	6789BR	
Hydro. Drive .....	07211500	6448BR	
<b>ZTXL42</b>			
Deck Drive .....	07200523	7089BR	
Transaxle .....	07200724	7074BR	
<b>ZTXL52</b>			
Deck Drive .....	07200023	6708BR	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAVELY - Continued</b>			
<b>ZTXL52 – Continued</b>			
Transaxle .....	07200724		7074BR
<b>ZTXL60</b>			
Deck Drive .....	07200804		6979BR
Transaxle .....	07200724		7074BR
<b>GRAZER</b>			
<b>1600; 1800</b>			
Trans. ....	9003000		6838
<b>2297K</b>			
P.T.O. ....	C44241		6956
<b>G100</b>			
Trans. ....	9003000		6838
<b>G1142</b>			
Blade .....	9003003		6895
Deck .....	9003002		6855
Trans. ....	9003000		6838
<b>G1250 Chain Drive Model</b>			
Trans. ....	9003000		6838
<b>G1250 Direct Drive Model</b>			
Trans. ....	9003011		6839
<b>G1250H Chain Drive Model</b>			
Trans. ....	9003000		6838
<b>G1250H Direct Drive Model</b>			
Trans. ....	9003011		6839
<b>G1600</b>			
Trans. ....	9003000		6838
<b>G1642</b>			
Blade; W/48" Belt O.C. ....	9003007		6848
Blade; W/53" Belt O.C. ....	9003006		6853
Deck .....	9003004		6854
Trans. ....	9003000		6838
<b>G1652</b>			
Deck .....	9003004		6854
Trans. ....	9003000		6838
<b>G1800; G1852</b>			
Trans. ....	9003000		6838
<b>G1862</b>			
Dual Deck Drive .....	9003009		6858
Trans. ....	9003000		6838
<b>G1890; G1890K</b>			
Eng. To Cross Shaft .....	9003010		6835
Pump Drive .....	9003027		6826
<b>G2000CII</b>			
Pump Drive .....	9003022		6850
<b>GREAT DANE</b>			
<b>GBKH2752S</b>			
Deck Drive .....	TCU16093		6598BR
Hydro. Drive .....	D28125		6914BR
<b>GBKH2761S</b>			
Deck Drive .....	GDU10228		6950BR
Hydro. Drive .....	D28125		6914BR
<b>GBKW2552S</b>			
Deck Drive .....	TCU16093		6598BR
Hydro. Drive .....	D28125		6914BR
<b>GBKW2561S; GCBR2652S; GCBR2661S</b>			
Deck Drive .....	GDU10228		6950BR
Hydro. Drive .....	D28125		6914BR
<b>GCBV2348S</b>			
Deck Drive .....	TCU16092		6745BR
Hydro. Drive .....	D28125		6914BR
<b>GCBV2361S</b>			
Deck Drive .....	GDU10228		6950BR
Hydro. Drive .....	D28125		6914BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GREAT DANE - Continued</b>			
<b>GCKA1948S</b>			
Deck Drive .....	TCU16092		6745BR
Hydro. Drive .....	D28125		6914BR
<b>GCKA1952S</b>			
Deck Drive .....	GDU10228		6950BR
Hydro. Drive .....	D28125		6914BR
<b>GCKH2348S</b>			
Deck Drive .....	TCU16092		6745BR
Hydro. Drive .....	D28125		6914BR
<b>GCKH2352S; GCKH2361S</b>			
Deck Drive .....	GDU10228		6950BR
Hydro. Drive .....	D28125		6914BR
<b>GCKW2352S</b>			
Deck Drive .....	TCU16093		6598BR
Hydro. Drive .....	D28125		6914BR
<b>GCKW2561S</b>			
Deck Drive .....	GDU10228		6950BR
Hydro. Drive .....	D28125		6914BR
<b>GSKA1948S; GSKH1848S</b>			
Deck Drive .....	TCU18847		6949BR
Hydro. Drive .....	GDU10025		6559BR
<b>GSKH2352S</b>			
Deck Drive .....	TCU18848		6492BR
Hydro. Drive .....	GDU10025		6559BR
<b>GSKH2561S</b>			
Deck Drive .....	TCU18849		6901BR
Hydro. Drive .....	GDU10025		6559BR
<b>GSKW1948S</b>			
Deck Drive .....	TCU18847		6949BR
Hydro. Drive .....	GDU10025		6559BR
<b>GSKW2352S</b>			
Deck Drive .....	TCU18848		6492BR
Hydro. Drive .....	GDU10025		6559BR
<b>GSRKA1934S</b>			
Deck Drive .....	00201010		6815BR
<b>GSRKA1952S; GSRKA2352S</b>			
Deck Drive .....	TCU18848		6492BR
Hydro. Drive .....	GDU10025		6559BR
<b>TCLX61-25KAE; TCLX61-25KHE;</b>			
<b>TCLX61-26KHE; TCLX61-27KHE;</b>			
<b>TCLX61-28KHE</b>			
Deck Drive .....	GDU10228		6950BR
Hydro. Drive .....	D28125		6914BR
<b>TCLX72-27KHE; TCLX72-28KHE</b>			
Blade Drive .....	D28028		6622BR
Eng. To Deck .....	GDU10229		6994BR
Hydro. Drive .....	D28125		6914BR
<b>TCRZ48-17KAE; TCRZ48-19KAE</b>			
Deck Drive .....	TCU16092		6745BR
Hydro. Drive .....	D28125		6914BR
<b>TCRZ52-23KAE; TCRZ52-25KAE;</b>			
<b>TCRZ52-25KHE</b>			
Deck Drive .....	TCU16093		6598BR
Hydro. Drive .....	D28125		6914BR
<b>TCRZ61-25KAE; TCRZ61-25KHE</b>			
Deck Drive .....	GDU10228		6950BR
Hydro. Drive .....	D28125		6914BR
<b>GRILLO</b>			
<b>507 Dumper</b>			
P.T.O. ....	6635	9590	9590HD
<b>GUYBROD-GERMANY</b>			
<b>2652-1</b>			
Variator To Trans. ....	7540136		6931
<b>2652-2</b>			
Blade .....	7540127		6966

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GUYBROD-GERMANY - Continued</b>			
<b>2652-2 - Continued</b>			
Variator To Trans. ....	7540136		6931
<b>HAHN ECLIPSE</b>			
<b>3900; 3901; 3902; 3903</b>			
Blade .....	308476		6870
Transaxle .....	308475		6831
<b>3909; 3910; 3911</b>			
Blade .....	308493		6869
<b>3912; 3914</b>			
Blade .....	308494		6866
<b>3915</b>			
Blade .....	308493		6869
<b>3916; 3917</b>			
Blade .....	308494		6866
<b>3919</b>			
Blade .....	308493		6869
Transaxle .....	308506		6731
<b>3921; 3922</b>			
Blade .....	308505		6870
Eng. ....	308504		6879
Transaxle .....	308506		6731
<b>3929; 3933; 3934; 3935; 3936; 3937; 3938</b>			
Blade .....	308494		6866
<b>3942; 3943</b>			
Blade .....	308493		6869
<b>3948; 3949</b>			
Blade .....	308505		6870
Eng. ....	308504		6879
<b>3953</b>			
Blade .....	308510		6856
Trans. ....	308511		6838
<b>3955</b>			
Blade .....	308493		6869
<b>3956</b>			
Blade .....	308505		6870
Eng. ....	308504		6879
<b>3957; 3958</b>			
Blade .....	308493		6869
<b>3959</b>			
Blade; W/56" Belt O.C. ....	308510		6856
Blade; W/69" Belt O.C. ....	308493		6869
Trans. ....	308511		6838
<b>3960; 3961; 3962</b>			
Blade .....	308494		6866
<b>3966; 3967</b>			
Blade .....	308510		6856
Trans. ....	308511		6838
<b>3968; 3969</b>			
Blade .....	308493		6869
<b>3970</b>			
Blade .....	308521		6865
<b>3971; 3973</b>			
Blade .....	308522		6867
<b>3976; 3977</b>			
Blade .....	308510		6856
Trans. ....	308511		6838
<b>3979; 3980; 3981; 3984</b>			
Blade .....	308493		6869
<b>3988</b>			
Blade .....	308522		6867
<b>4070; 4071; 4077; 4078; 4079; 4080; 4081;</b>			
<b>4082; 4084</b>			
Blade .....	308437		6848

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HAHN ECLIPSE - Continued</b>			
<b>4085</b>			
Belt; W/53" Belt O.C. ....	308443		6853
Belt; W/72" Belt O.C. ....	308444		6872
<b>4086; 4088; 4089; 4091; 4092; 4093; 4094; 4095; 4096; 4097</b>			
Belt .....	308442		6848
<b>4102; 4103</b>			
Belt .....	308442		6848
<b>4200; 4203</b>			
Blade .....	308457		6841
Drive .....	308455		6886
J.S. ....	308456		6831
<b>9004; 9005; 9008; 9009; 9010</b>			
Blade .....	308437		6848
<b>9016; 9017; 9018; 9019</b>			
Belt .....	308442		6848
<b>9023; 9024</b>			
Blade .....	308481		6853
Trans. ....	308480		6835
<b>9025; 9026</b>			
Blade .....	308483		6853
Eng. ....	308482		6860
Trans. ....	308480		6835
<b>9027; 9028</b>			
Blade .....	308481		6853
Trans. ....	308480		6835
<b>9029</b>			
Blade .....	308483		6853
Eng. ....	308482		6860
Trans. ....	308480		6835
<b>9034</b>			
Blade .....	308493		6869
<b>9035; 9036</b>			
Blade .....	308494		6866
<b>9037; 9038; 9039</b>			
Blade .....	308493		6869
<b>9040; 9041; 9042; 9043</b>			
Blade .....	308493		6869
Transaxle .....	308506		6731
<b>9044; 9045; 9046; 9047</b>			
Blade .....	308494		6866
Transaxle .....	308506		6731
<b>EH326; EH332</b>			
Blade .....	308389		6745
Reverse .....	308390		3V335
Traction .....	308400		6837
<b>EHD130; EHE130</b>			
Traction .....	308475		6831
<b>PH326; PH332; PP326</b>			
Blade .....	308389		6745
Reverse .....	308390		3V335
Traction .....	308400		6837
<b>RH736</b>			
J.S. ....	308456		6831
Wheel Drive .....	308455		6886
<b>RHDE836; RHDE1236</b>			
J.S. ....	308456		6831
Wheel Drive .....	308464		6878
<b>RHE736</b>			
J.S. ....	308456		6831
Wheel Drive .....	308455		6886
<b>RHSE1236</b>			
J.S. ....	308456		6831
Wheel Drive .....	308464		6878

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HARDWARE WHOLESALERS, INC.</b>			
<b>131-412</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>131-435</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>131-480</b>			
Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
<b>132-380</b>			
Blade .....	7540138	3500	6950
Drive .....	7540164	2630	6863
<b>132-412</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>132-435</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>132-480</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>134-380</b>			
Blade .....	7540138	3500	6950
Drive .....	7540164	2630	6863
<b>134-395</b>			
Drive .....	7540164	2630	6863
<b>134-400</b>			
Blade .....	7540188		6951
Drive .....	7540101		6517BR
<b>134-495</b>			
Blade .....	7540145		6488BR
Drive .....	7540173	3370	6937
<b>134-501</b>			
Blade .....	7540249		6930
Trans. ....	7540264		6639BR
<b>134-504</b>			
Eng. To Deck .....	7540264		6639BR
Primary Variator .....	7540241		6494BR
Secondary Variator .....	7540240		6511BR
<b>134-668</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>135-360</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>135-402</b>			
Blade .....	7540188		6951
Drive .....	7540136		6931
<b>135-465</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>136-360</b>			
Blade .....	7540107		6830
Trans. ....	7540935	2310	6831
<b>136-400</b>			
Blade .....	7540188		6951
Drive .....	7540101		6517BR
<b>136-435</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HARDWARE WHOLESALERS, INC. - Continued</b>			
<b>136-465</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>136-497</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>136-525</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>137-360</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>137-400</b>			
Blade .....	7540188		6951
Drive .....	7540101		6517BR
<b>137-435</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>137-475</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>137-497</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>138-460</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>141-669; 142-669</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>144-836</b>			
Blade .....	7540230		6755BR
Deck .....	7540246		6354
Drive; W/40" Belt O.C. ....	7540244		6840
Drive; W/59" Belt O.C. ....	7540245		6859
<b>HEALD</b>			
<b>TR-8</b>			
Clutch .....	203022		6872
<b>HOMELITE</b>			
<b>LT-10; LT-12; LT13</b>			
Traction .....	JA392594		6896
<b>T7; T8</b>			
Drive .....	1607967		6639BR
Trans.; W/48" Belt O.C. ....	108428		6848
Trans.; W/76" Belt O.C. ....	162081		6876
<b>T12; T15</b>			
Trans. ....	108428		6848
<b>T16H; T16S</b>			
Drive; W/34" Belt O.C. ....	174883		6834
Drive; W/53" Belt O.C. ....			6853
Trans. ....	108428		6848
<b>YT-12; YT-14</b>			
Traction .....	JA992249		A110
<b>HOMESTEADER</b>			
<b>1100; 1600; D-7</b>			
Mower; W/80" Belt O.C. ....			6880
Mower; W/84" Belt O.C. ....			6884
Traction .....			6953

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HOMKO</b>			
<b>1414 AMF Trac</b>			
P.T.O. ....	1501245		6887
Tiller Attachment .....	1501105		6951
<b>1234000</b>			
Blade .....	20368	2290	
<b>5254000</b>			
Blade .....	29798		6827
<b>12370100; 12370200; 12380000; 12380200</b>			
Blade .....	20368	2290	
Drive .....	23164		6825
<b>12470200</b>			
Blade .....	20368	2290	
<b>12620000</b>			
Blade .....	29281	3780	
<b>12650000</b>			
Blade .....	30839	3730	
<b>12660000; 12660300; 12660600; 12660700; 12660800; 12660900; 12661000</b>			
Blade .....	26659	3720	
<b>12661100</b>			
Blade .....	26659		6972
<b>12670000; 12670100; 12680000</b>			
Blade .....	26659	3720	
<b>12700000</b>			
Blade .....	31053		6827
Transaxle .....	30997		6847
<b>12720000</b>			
Blade .....	31053		6827
Transaxle .....	30998		6842
<b>52360400</b>			
Blade .....	20368	2290	
<b>52380000; 52383200; 52384000</b>			
Blade .....	20368	2290	
Drive .....	23164		6825
<b>52390000; 52400200</b>			
Blade .....	20368	2290	
<b>52403000; 52443000; 52443200; 52443400</b>			
Blade .....	20368	2290	
Drive .....	23164		6825
<b>52463000; 52463100</b>			
Blade .....	26659	3720	
<b>52550000; 52580000</b>			
Blade .....	29798		6827
<b>52700200</b>			
Blade .....	31053		6827
Transaxle .....	30997		6847
<b>52710100; 52710200</b>			
Blade .....	31053		6827
Transaxle .....	30998		6842
<b>HONDA</b>			
<b>3011; 3013</b>			
Deck .....			6973
Trans. ....			6953
<b>HA4118H38A</b>			
Blade Drive .....	76181-V09-A01		6943BR
P.T.O. ....	76182-V09-A01		7097BR
Trans. ....	22431-V09-A01		6653BR
<b>HA4120H48A</b>			
P.T.O. ....	76182-V09-D01		6818BR
Trans. ....	22431-V09-A01		6653BR
<b>HT3810; HT3810K1</b>			
Blade .....	76181750003		6966
Eng. To Deck .....	76182750003		B105

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HONDA - Continued</b>			
<b>HT3813</b>			
Blade .....	76181750003		6966
Eng. To Deck .....	76182750003		B105
P.T.O. ....	76181750003		6966
<b>HTR3009</b>			
Blade .....	76181750003		6966
Eng. To Deck .....	76181751003		6971
Trans. ....			6953
<b>HTR3811</b>			
Blade .....	761847517		6963
Deck .....	76181751701		6967
<b>HOWARD PRICE</b>			
<b>422</b>			
Fan & Alt. ....	22088	7350	
<b>727</b>			
Gov. ....	7334	7334	
<b>4845; 4876; 6072; 6074; 6075; 6076; 8274; 8275; 8276</b>			
Belt; W/48", 60", 72" Deck .....	3200		6820
<b>Deck</b>			
Belt; W/44" Belt O.C. ....	07430		6844
<b>Wing Deck</b>			
Belt; W/57" Belt O.C. ....	07433		6857
<b>HUFFMAN</b>			
<b>0822; 0826</b>			
Blade; W/51" Belt O.C. ....	15318	2500	
Blade; W/52" Belt O.C. ....	15482	2520	6852
Trans. ....	15342		6855
<b>0855</b>			
Drive; W/29" Belt O.C. ....	8671B		6829
Drive; W/31" Belt O.C. ....	9407B		6831
<b>0862</b>			
Blade .....	19887	2550	6855
Drive .....	19855	2350	6835
<b>0867</b>			
Drive; W/29" Belt O.C. ....	8671B		6829
Drive; W/31" Belt O.C. ....	9407B		6831
<b>1010; 1014</b>			
Trans. ....	8671B		6829
<b>1025</b>			
Trans. ....	9407B		6831
<b>1050; 1052; 1054; 1055; 1060; 1061; 1070</b>			
Trans. ....	8671B		6829
<b>1080; 1081; 1090; 1091</b>			
Blade .....	15318	2500	
Trans. ....	15342		6855
<b>1110; 1111</b>			
Trans. ....	15342		6855
<b>1443; 1444</b>			
Drive; W/29" Belt O.C. ....	8671B		6829
Drive; W/31" Belt O.C. ....	9407B		6831
<b>1501; 1511; 1521; 1531</b>			
Blade .....	19887	2550	6855
Trans. ....	19855	2350	6835
<b>1541</b>			
Trans. ....	19855	2350	6835
<b>2822; 2826</b>			
Blade; W/50" Belt O.C. ....	15318	2500	6850
Blade; W/51" Belt O.C. ....	15318	2510	6851
Blade; W/52" Belt O.C. ....	15482	2520	6852
Trans. ....	15342		6855
<b>2863</b>			
Blade .....	19887	2550	6855
Drive .....	19855	2350	6835

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUFFMAN - Continued</b>			
<b>2866; 2867; 4442</b>			
Drive; W/29" Belt O.C. ....	8671B		6829
Drive; W/31" Belt O.C. ....	9407B		6831
<b>4822; 4826</b>			
Blade; W/50" Belt O.C. ....	15318	2500	6850
Blade; W/51" Belt O.C. ....	15318	2510	6851
Blade; W/52" Belt O.C. ....	15482	2520	6852
Trans. ....	15342		6855
<b>4833; 4846; 4847</b>			
Drive; W/29" Belt O.C. ....	8671B		6829
Drive; W/31" Belt O.C. ....	9407B		6831
<b>4862; 4863</b>			
Blade .....	19887	2550	6855
Drive .....	19855	2350	6835
<b>4866; 4867; 4868; 9442; 9443; 9444</b>			
Drive; W/29" Belt O.C. ....	8671B		6829
Drive; W/31" Belt O.C. ....	9407B		6831
<b>HUSKEE</b>			
<b>LT 38</b>			
Deck Drive .....	954-04062		6774BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-04265		6934
<b>LT 42</b>			
Deck Drive .....	954-04060B		6776BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-0241A		6494BR
<b>HUSQVARNA</b>			
<b>2042LS</b>			
Deck .....	532144959		6758BR
Drive .....	532130969		6757BR
<b>2146XLS; 2246LS; 2346XLS</b>			
Deck .....	532405143		6821BR
Drive .....	532130969		6757BR
<b>2348LS</b>			
Deck .....	532197242		6786BR
Drive .....	532130969		6757BR
<b>2354GXLS</b>			
Deck .....	532196103		6767BR
Drive .....	532125907		6713BR
<b>2748GLS</b>			
Deck .....	532197242		6786BR
Drive .....	532420807		6558BR
<b>2754GLS</b>			
Deck .....	532196103		6767BR
Drive .....	532420807		6558BR
<b>BZ6127; BZ6127TD</b>			
Deck .....	539106340		6692BR
<b>BZ7234; BZ7234TD</b>			
Deck .....	539104335		6760BR
<b>CTH130</b>			
Deck .....	532165555		6456BR
Drive .....	532165632		6928BR
<b>CTH150</b>			
Deck .....	532169178		6749BR
Drive .....	532165632		6928BR
<b>CZ3815</b>			
Deck Drive .....	539110413		6651BR
Hydro. Drive .....	539110411		6755BR
<b>CZ4217</b>			
Deck Drive .....	539110410		6810BR
Hydro. Drive .....	539110411		6755BR
<b>CZ4815; CZ4817; CZ4818</b>			
Deck Drive .....	539107709		6783BR
Hydro. Drive .....	539107710		6943BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSQVARNA - Continued</b>			
<b>EZ3417</b>			
Deck Drive .....	539117811		6858BR
Hydro. Drive .....	539118012		6896BR
<b>EZ4217; EZ4220</b>			
Deck .....	539112334		6566BR
Hydro. Pump .....	539104334		6756BR
<b>EZ4624</b>			
Hydro. Pump .....	539104334		6756BR
<b>EZ4819</b>			
Deck .....	539110832		6759BR
Hydro. Pump .....	539104334		6756BR
<b>EZ4824</b>			
Deck .....	539103013		6778BR
Hydro. Pump .....	539120772		6793BR
<b>EZ4824K</b>			
Deck .....	539103013		6778BR
Hydro. Pump .....	539101957		6425BR
<b>EZ5221</b>			
Deck; Model No. 965880501 .....	539107709		6783BR
Deck; Model No. 968999292 .....	539112335		6746BR
Hydro. Pump; Model No. 965880501 .....	539101957		6425BR
Hydro. Pump; Model No. 968999292 .....	539104334		6756BR
<b>EZ5224</b>			
Deck; Model No. 965880601 .....	539107709		6783BR
Deck; Model No. 968999699 .....	539112335		6746BR
Hydro. Pump; Model No. 965880601 .....	539101957		6425BR
Hydro. Pump; Model No. 968999699 .....	539104334		6756BR
<b>EZ5226</b>			
Deck; Model No. 965921601 .....	539107709		6783BR
Deck; Model No. 968999658 .....	539112335		6746BR
Hydro. Pump; Model No. 965921601 .....	539120772		6793BR
Hydro. Pump; Model No. 968999658 .....	539104334		6756BR
<b>EZ5426</b>			
Deck .....	539112333		6598BR
Hydro. Pump .....	539104334		6756BR
<b>EZ6124</b>			
Hydro. Pump .....	539104334		6756BR
<b>EZC4824</b>			
Deck .....	539106340		6692BR
Hydro. Pump .....	539101957		6425BR
<b>GT48XLS</b>			
Deck Drive .....	574845602		6785BR
Drive .....	532125907		6713BR
<b>GT52XLS; GT52XLSi</b>			
Deck Drive .....	574845603		7057BR
Drive .....	532420807		6558BR
<b>GT54LS</b>			
Deck Drive .....	532196103		6767BR
Drive .....	532125907		6713BR
<b>GT2254</b>			
Deck Drive .....	532191273		6599BR
Drive .....	532137153		6798BR
<b>GTH24K54</b>			
Deck Drive .....	532196103		6767BR
Drive .....	532420807		6558BR
<b>GTH26K54T</b>			
Deck Drive .....	532196103		6767BR
Drive .....	532140218		6811BR
<b>GTH26V52LS</b>			
Deck Drive .....	574845603		7057BR
Drive .....	532420807		6558BR
<b>GTH27V48LS</b>			
Deck Drive .....	574845602		6785BR
Drive .....	532420807		6558BR
<b>GTH200</b>			
Drive .....	532140218		6811BR
Primary .....	532148763		6702BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSQVARNA - Continued</b>			
<b>GTH200 - Continued</b>			
Secondary .....	532144959		6758BR
<b>GTH220</b>			
Drive .....	532140218		6811BR
Primary .....	532139573		6798BR
Secondary .....	532144959		6758BR
<b>GTH225</b>			
Drive .....	532140218		6811BR
Primary .....	532148763		6702BR
Secondary .....	532144959		6758BR
<b>GTH250</b>			
Drive .....	532140218		6811BR
Primary .....	532139573		6798BR
Secondary .....	532144959		6758BR
<b>GTH2248XP</b>			
Drive .....	532161597		6551BR
Primary .....	532174368		6649BR
Secondary .....	532180808		6614BR
<b>GTH2250</b>			
Drive .....	532161597		6551BR
Primary .....	532139573		6798BR
Secondary .....	532144959		6758BR
<b>GTH2254XP</b>			
Deck .....	532191273		6599BR
Drive .....	532161597		6551BR
<b>GTH2448T</b>			
Deck Drive .....	532197242		6786BR
Drive .....	532140218		6811BR
<b>GTH2454T</b>			
Deck Drive .....	532196103		6767BR
Drive .....	532140218		6811BR
<b>GTH2548</b>			
Drive .....	532161597		6551BR
Primary .....	532174368		6649BR
Secondary .....	532180808		6614BR
<b>GTH2548XP</b>			
Drive .....	532161597		6551BR
Primary .....	532174368		6649BR
Secondary .....	532174369		6614BR
<b>GTH2550</b>			
Drive .....	532140218		6811BR
Primary .....	532139573		6798BR
Secondary .....	532144959		6758BR
<b>GTH2550XP</b>			
Drive .....	532161597		6551BR
Primary .....	532139573		6798BR
Secondary .....	532144959		6758BR
<b>GTH2554XP</b>			
Deck .....	532191273		6599BR
Drive .....	532161597		6551BR
<b>GTH2648</b>			
Deck Drive .....	532197242		6786BR
Drive .....	532125907		6713BR
<b>GTH2654</b>			
Deck Drive .....	532191273		6599BR
Drive .....	532161597		6551BR
<b>GTH2654T</b>			
Deck Drive .....	532196103		6767BR
Drive .....	532140218		6811BR
<b>GTH2754</b>			
Deck Drive .....	532191273		6599BR
Drive .....	532161597		6551BR
<b>GTVH200; GTVH205</b>			
Drive .....	532161741		6672BR
Primary .....	532148763		6702BR
Secondary .....	532144959		6758BR
<b>IZ4217; IZ4217T</b>			
Deck .....	539110832		6759BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSQVARNA - Continued</b>			
IZ4817T; IZ4819; IZ4821T Deck .....	539111949		6732BR
IZ5223T; IZ5225TXP Blower .....	539111306		6528BR
IZ6123T; IZ6125; IZ6125T Deck .....	539108656		7031BR
LGT24K54 Deck Drive .....	532196103		6767BR
Drive .....	532130969		6757BR
LGT2554; LGT2654 Deck .....	532196103		6767BR
Drive .....	532130969		6757BR
LSZ4622 Deck Drive .....	539117245		6589BR
Hydro. Drive .....	539120772		6793BR
LSZ5422 Deck Drive .....	539114557		6597BR
Hydro. Drive .....	539120772		6793BR
LSZ5424 Deck Drive .....	539114557		6597BR
LT1238 Deck .....	532144200		6463BR
Drive .....	532130801		6758BR
LT1538 Deck Drive .....	532144200		6463BR
Drive .....	532130801		6758BR
LT18542 Deck .....	532144959		6758BR
Drive .....	532130801		6758BR
LTA18538 Deck Drive .....	532408381		6776BR
Drive .....	532197253		7015BR
LTH130 Deck Drive .....	532144200		6463BR
LTH1342 Deck .....	532144959		6758BR
Drive .....	532140294		6434BR
LTH1438; LTH1538 Deck .....	532408381		6776BR
Drive .....	532125907		6713BR
LTH1542 Deck .....	532174883		6721BR
Drive .....	532140294		6434BR
LTH1742 Deck Drive .....	532144959		6758BR
Drive .....	532140294		6434BR
LTH1842 Deck Drive .....	532174883		6721BR
Drive .....	532140294		6434BR
LTH2038 Deck Drive .....	532408381		6776BR
LTH2042 Deck .....	532144959		6758BR
Drive .....	532140294		6434BR
LTH18538 Deck Drive .....	532408381		6776BR
Drive .....	532130969		6757BR
LTH18542 Deck .....	532144959		6758BR
Drive .....	532140294		6434BR
LZ5225 Hydro. Pump .....	510201501		6756BR
LZ5225T Deck .....	539104335		6760BR
Hydro. Pump .....	539104334		6756BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSQVARNA - Continued</b>			
LZ5227 Hydro. Pump .....	510201501		6756BR
LZ5227TXP Deck .....	539104335		6760BR
Hydro. Pump .....	539104334		6756BR
LZ6125T Deck .....	539104336		6761BR
Hydro. Pump .....	539104334		6756BR
LZ6127 Deck .....	510201301		6761BR
Hydro. Pump .....	510201501		6756BR
LZ6127T Deck .....	539104336		6761BR
Hydro. Pump .....	539104334		6756BR
LZ6130 Deck .....	510201301		6761BR
Hydro. Pump .....	510201501		6756BR
LZ6130TXP Deck .....	539104336		6761BR
Hydro. Pump .....	539104334		6756BR
LZ7227T Deck .....	539105477		6934BR
Hydro. Pump .....	539104334		6756BR
LZ7230 Hydro. Pump .....	510201501		6756BR
LZ7230TXP Deck .....	539105477		6934BR
Hydro. Pump .....	539104334		6756BR
LZF5227 Deck .....	539104335		6760BR
Hydro. Pump .....	539104334		6756BR
LZF6127 Deck .....	539104336		6761BR
Hydro. Pump .....	539104334		6756BR
MZ 52 Deck Drive .....	539107095		7069BR
Hydro. Drive .....	574870901		7007BR
MZ 54S Deck Drive .....	577503601		6983BR
Hydro. Drive .....	574870901		7007BR
MZ 61 Deck Drive .....	539104335		6760BR
Hydro. Drive .....	574870901		7007BR
MZ5225 Deck .....	539114557		6597BR
Hydro. Pump .....	539111445		6553BR
MZ5225ZT Deck Drive .....	522811301		6692BR
Hydro. Drive .....	574870901		7007BR
MZ5226 Deck .....	539114557		6597BR
Hydro. Pump .....	539111445		6553BR
MZ5424S Deck Drive .....	577503601		6983BR
Hydro. Drive .....	574870901		7007BR
MZ6125 Deck .....	539132002		6747BR
Hydro. Pump .....	539111445		6553BR
MZ6128; MZ6128ZT Deck Drive .....	539104335		6760BR
Hydro. Drive .....	574870901		7007BR
MZ7227 Deck .....	539132003		6881BR
Hydro. Pump .....	539111445		6553BR
M-ZT 52 Deck Drive .....	522811301		6692BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSQVARNA - Continued</b>			
<b>M-ZT 52 - Continued</b>			
Hydro. Drive .....	574870901		7007BR
<b>M-ZT 61</b>			
Deck Drive .....	539104335		6760BR
Hydro. Drive .....	574870901		7007BR
<b>PZ 54</b>			
Deck Drive .....	575658401		7034BR
Hydro. Drive .....	573978301		6675BR
<b>PZ 60</b>			
Deck Drive; 2013 & Older .....	575658403		6938BR
Deck Drive; 2014 & Newer .....	588264801		6938BR
Hydro. Drive .....	573978301		6675BR
<b>PZ 60P</b>			
Deck Drive .....	575658403		6938BR
Hydro. Drive .....	573978301		6675BR
<b>PZ 72</b>			
Deck Drive .....	575658405		7002BR
Hydro. Drive .....	573978301		6675BR
<b>PZ5426FX</b>			
Deck Drive .....	574285901		6878BR
Hydro. Drive .....	573978301		6675BR
<b>PZ6029D</b>			
Deck Drive .....	522860201		6935BR
Hydro. Pump .....	574890001		6930BR
<b>PZ6029FX; PZ6029PFX; PZ6030CV; PZ6034FX; PZ6034FXZT</b>			
Deck Drive .....	522829601		6879BR
Hydro. Drive .....	573978301		6675BR
<b>PZ7234FX</b>			
Deck Drive .....	574286001		6882BR
Hydro. Drive .....	573978301		6675BR
<b>P-ZT 48</b>			
Hydro. Drive .....	576667201		7024BR
<b>P-ZT 54</b>			
Deck Drive .....	575658401		7034BR
Hydro. Drive .....	576667201		7024BR
<b>P-ZT 60</b>			
Deck Drive; 2013 & Older .....	575658401		7034BR
Deck Drive; 2014 & Newer .....	588264801		6938BR
Hydro. Drive .....	576667201		7024BR
<b>P-ZT4822; P-ZT5224; P-ZT6126; P-ZT6128</b>			
Hydro. Drive .....	576667201		7024BR
<b>R 220T; R 322T AWD</b>			
Deck Drive; W/44" Deck .....	535411901		6551BR
Deck Drive; W/48" Deck .....	532180213		6798BR
<b>RZ3016</b>			
Deck Drive; 2012 & Older .....	574173002		68100
Hydro. Drive .....	539120806		7026BR
<b>RZ4216</b>			
Deck Drive .....	574173003		6715BR
Hydro. Drive .....	575852401		7027BR
<b>RZ4219</b>			
Deck Drive; 2008 & Older .....	539110410		6810BR
Deck Drive; 2009 .....	522999901		6980BR
Deck Drive; 2012 & Older .....	574173003		6715BR
Deck Drive; 2013 & Newer .....	581805901		6923BR
Hydro. Pump; 2009 & Older .....	539110411		6755BR
Hydro. Pump; 2010 & Newer .....	575852401		7027BR
<b>RZ4219F; RZ4222F</b>			
Deck Drive .....	539117245		6589BR
Hydro. Drive .....	539110411		6755BR
<b>RZ4619; RZ4620</b>			
Deck .....	539117245		6589BR
Hydro. Pump .....	539110411		6755BR
<b>RZ4621; RZ4623</b>			
Deck Drive .....	539117245		6589BR
Hydro. Drive .....	539110411		6755BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSQVARNA - Continued</b>			
<b>RZ4824F</b>			
Deck Drive .....	539109243		6785BR
Hydro. Drive .....	539110411		6755BR
<b>RZ5422; RZ5424</b>			
Deck .....	539114557		6597BR
Hydro. Pump .....	539110411		6755BR
<b>RZ5426</b>			
Deck Drive .....	539114557		6597BR
Hydro. Drive .....	539110411		6755BR
<b>SRD17530</b>			
Deck Drive .....	532419271		6463BR
Drive .....	532138255		6758BR
<b>YT42CS</b>			
Deck Drive .....	532144959		6758BR
Drive .....	532130969		6757BR
<b>YT42DXLS</b>			
Drive .....	532130969		6757BR
<b>YT42LS</b>			
Deck Drive .....	532144959		6758BR
Drive .....	532130969		6757BR
<b>YT42XLS</b>			
Deck Drive .....	574845601		6901BR
Drive .....	532130969		6757BR
<b>YT46LS</b>			
Deck Drive .....	532405143		6821BR
Drive .....	532130969		6757BR
<b>YT48CS</b>			
Deck Drive .....	532197242		6786BR
Drive .....	532130969		6757BR
<b>YT48XLS</b>			
Deck Drive .....	574845602		6785BR
Drive .....	532130969		6757BR
<b>YT54LS</b>			
Deck Drive .....	532196103		6767BR
Drive .....	532130969		6757BR
<b>YTA19K42</b>			
Deck Drive .....	532429636		6653BR
Drive .....	532197253		7015BR
<b>YTA22V46</b>			
Deck Drive .....	532405143		6821BR
Drive .....	532197253		7015BR
<b>YTA18542</b>			
Deck Drive .....	532429636		6653BR
Drive .....	532197253		7015BR
<b>YTH18K46</b>			
Deck Drive .....	532405143		6821BR
Drive .....	532130969		6757BR
<b>YTH20B42T</b>			
Deck Drive .....	532144959		6758BR
Drive .....	532140218		6811BR
<b>YTH20F42T</b>			
Deck Drive .....	532144959		6758BR
Drive .....	532130969		6757BR
<b>YTH20K46</b>			
Deck .....	532405143		6821BR
Drive .....	532125907		6713BR
<b>YTH21K46</b>			
Deck Drive .....	532405143		6821BR
Drive .....	532130969		6757BR
<b>YTH22V42</b>			
Deck Drive .....	532429636		6653BR
Drive .....	532130969		6757BR
<b>YTH22V42LS</b>			
Deck Drive .....	574845601		6901BR
Drive .....	532130969		6757BR

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSQVARNA - Continued</b>			
<b>YTH22V46; YTH22V46XLS</b>			
Deck Drive .....	532405143		6821BR
Drive .....	532130969		6757BR
<b>YTH23V42</b>			
Deck Drive .....	532429636		6653BR
Drive .....	532130969		6757BR
<b>YTH23V48; YTH24K48</b>			
Deck Drive .....	532197242		6786BR
Drive .....	532130969		6757BR
<b>YTH24V42LS</b>			
Deck Drive .....	574845601		6901BR
Drive .....	532130969		6757BR
<b>YTH24V48</b>			
Deck Drive .....	532197242		6786BR
Drive .....	532130969		6757BR
<b>YTH24V48LS</b>			
Deck Drive .....	574845602		6785BR
Drive .....	532130969		6757BR
<b>YTH24V54; YTH24V54XLS; YTH26V54</b>			
Deck Drive .....	532196103		6767BR
Drive .....	532130969		6757BR
<b>YTH1342XP</b>			
Deck Drive .....	532174883		6721BR
Drive .....	532140294		6434BR
<b>YTH1542XP</b>			
Deck .....	532144959		6758BR
Drive .....	532130969		6757BR
<b>YTH1542XPT</b>			
Deck Drive .....	532144959		6758BR
Drive .....	532130969		6757BR
<b>YTH1842</b>			
Deck Drive .....	532174883		6721BR
Drive .....	532140294		6434BR
<b>YTH1848XP</b>			
Drive .....	532140294		6434BR
Primary .....	532174368		6649BR
Secondary .....	532180808		6614BR
<b>YTH1848XPT</b>			
Deck .....	532197242		6786BR
Drive .....	532130969		6757BR
<b>YTH1942T</b>			
Deck Drive .....	532197253		7015BR
Drive .....	532194346		6765BR
<b>YTH2042</b>			
Deck .....	532197253		7015BR
Drive .....	532130969		6757BR
<b>YTH2046</b>			
Drive .....	532140294		6434BR
Primary .....	532148763		6702BR
Secondary .....	532144959		6758BR
<b>YTH2048</b>			
Drive .....	532140294		6434BR
Primary .....	532174368		6649BR
Secondary .....	532174369		6614BR
<b>YTH2146XP</b>			
Deck .....	532405143		6821BR
Drive .....	532130969		6757BR
<b>YTH2148</b>			
Drive .....	532140294		6434BR
Primary .....	532174368		6649BR
Secondary .....	532180808		6614BR
<b>YTH2242</b>			
Deck Drive .....	532405143		6821BR
Drive .....	532130969		6757BR
<b>YTH2242T</b>			
Deck .....	532144959		6758BR
Drive .....	532140218		6811BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSQVARNA - Continued</b>			
<b>YTH2246</b>			
Deck .....	532405143		6821BR
Drive .....	532130969		6757BR
<b>YTH2248</b>			
Drive .....	532140294		6434BR
Primary .....	532174368		6649BR
Secondary .....	532180808		6614BR
<b>YTH2348</b>			
Deck .....	532197242		6786BR
Drive .....	532130969		6757BR
<b>YTH2448</b>			
Drive .....	532140294		6434BR
Primary .....	532174368		6649BR
Secondary .....	532180808		6614BR
<b>YTH2448T</b>			
Deck Drive .....	532197242		6786BR
Drive .....	532140218		6811BR
<b>YTH2454</b>			
Deck .....	532196103		6767BR
Drive .....	532130969		6757BR
<b>YTH2454T</b>			
Deck .....	532196103		6767BR
Drive .....	532140218		6811BR
<b>YTH2548; YTH2748</b>			
Drive .....	532140294		6434BR
Primary .....	532174368		6649BR
Secondary .....	532180808		6614BR
<b>YTH18542</b>			
Deck Drive .....	532429636		6653BR
<b>Z242F</b>			
Hydro. Drive .....	539110411		6755BR
<b>Z246; Z246i</b>			
Deck Drive .....	539117245		6589BR
Hydro. Drive .....	539110411		6755BR
<b>Z248F</b>			
Deck Drive .....	539109243		6785BR
Hydro. Drive .....	539110411		6755BR
<b>Z254; Z254i</b>			
Deck Drive .....	539114557		6597BR
Hydro. Drive .....	539110411		6755BR
<b>Z3815</b>			
Deck Drive .....	539110413		6651BR
Hydro. Drive .....	539110411		6755BR
<b>Z4217; Z4218</b>			
Deck Drive .....	539110410		6810BR
Hydro. Drive .....	539110411		6755BR
<b>Z4219; Z4220</b>			
Deck Drive .....	539110410		6810BR
Hydro. Pump .....	539110411		6755BR
<b>Z4619</b>			
Hydro. Pump .....	539110411		6755BR
<b>Z4818</b>			
Deck Drive .....	539107709		6783BR
Hydro. Drive .....	539107710		6943BR
<b>Z4822</b>			
Deck Drive .....	539109243		6785BR
Hydro. Drive .....	539110411		6755BR
<b>Z4824</b>			
Deck .....	539109243		6785BR
Hydro. Pump .....	539110411		6755BR
<b>Z5426</b>			
Deck .....	539110832		6759BR
Hydro. Pump .....	539110411		6755BR
<b>ZTH5221; ZTH5222; ZTH5223; ZTH5225</b>			
Deck .....	539104335		6760BR
Pump .....	539104334		6756BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSQVARNA - Continued</b>			
<b>ZTH6125; ZTH6126</b>			
Deck .....	539104336		6761BR
Pump .....	539104334		6756BR
<b>ZTH7226</b>			
Deck .....	539105477		6934BR
Pump .....	539104334		6756BR
<b>HUSTLER EXCEL</b>			
<b>3500; 3700</b>			
Deck Drive; W/60" Side Discharge			
Deck .....	791988		6906BR
Deck Drive; W/72" Side Discharge			
Deck .....	601715		6859BR
<b>ATZ 27/60</b>			
Deck Drive; W/Side Discharge .....	797720		6802BR
Hydro. Pump .....	781443		6793BR
<b>ATZ 31/72</b>			
Deck Drive .....	784207		6803BR
Hydro. Pump .....	601463		6890BR
<b>ATZ 35/60</b>			
Deck Drive .....	602744		6919BR
Hydro. Pump .....	603904		6502BR
<b>FasTrak 22/48</b>			
Deck Drive .....	791335		7057BR
Hydro. Pump .....	600979		6891BR
<b>FasTrak 23/48</b>			
Deck Drive .....	791335		7057BR
Hydro. Pump .....	605468		6890BR
<b>FasTrak 23/54</b>			
Deck Drive; 2014 & Older .....	789388		6732BR
Deck Drive; 2015 & Newer .....	786483		6692BR
Hydro. Pump; 2014 & Older .....	600979		6891BR
Hydro. Pump; 2015 & Newer .....	605468		6890BR
<b>FasTrak 24/60</b>			
Deck Drive; 2014 & Older .....	782292		6733BR
Hydro. Pump; 2014 & Older .....	600979		6891BR
Hydro. Pump; 2015 & Newer .....	605468		6890BR
<b>FasTrak 48"</b>			
Deck .....	791335		7057BR
Hydro. Pump .....	600979		6891BR
<b>FasTrak 54"</b>			
Deck .....	789388		6732BR
Hydro. Pump .....	600979		6891BR
<b>FasTrak SD 23/48</b>			
Deck Drive .....	791335		7057BR
Hydro. Pump .....	605468		6890BR
<b>FasTrak SD 23/54</b>			
Deck Drive .....	786483		6692BR
Hydro. Pump .....	605468		6890BR
<b>FasTrak SD 24/60</b>			
Hydro. Pump .....	605468		6890BR
<b>FasTrak SDX 22/48</b>			
Deck Drive .....	791335		7057BR
Hydro. Pump .....	605468		6890BR
<b>FasTrak SDX 22/54</b>			
Deck Drive .....	786483		6692BR
Hydro. Pump .....	605468		6890BR
<b>FasTrak SDX 23.5/60</b>			
Hydro. Pump .....	605468		6890BR
<b>FasTrak Super Duty 19/36</b>			
Deck Drive; 2012 & Older .....	600726		6684BR
Deck Drive; 2013 & Newer .....	771824		6923BR
Hydro. Pump .....	602253		6448BR
<b>FasTrak Super Duty 19/42</b>			
Deck Drive; 2012 & Older .....	793893		6486BR
Deck Drive; 2013 & Newer .....	603739		6977BR
Hydro. Pump .....	602253		6448BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSTLER EXCEL - Continued</b>			
<b>FasTrak Super Duty 21/48</b>			
Deck Drive .....	791335		7057BR
Hydro. Pump .....	600979		6891BR
<b>FasTrak Super Duty 21/54</b>			
Deck Drive .....	789388		6732BR
Hydro. Pump .....	600979		6891BR
<b>FasTrak Super Duty 21/60</b>			
Deck Drive .....	782292		6733BR
Hydro. Pump .....	600979		6891BR
<b>FasTrak Super Duty 22/48</b>			
Deck Drive .....	791335		7057BR
Hydro. Pump .....	600979		6891BR
<b>FasTrak Super Duty 23.5/54</b>			
Deck Drive .....	789388		6732BR
Hydro. Pump .....	600979		6891BR
<b>FasTrak Super Duty 23.5/60</b>			
Deck Drive .....	782292		6733BR
Hydro. Pump .....	600979		6891BR
<b>FasTrak Super Duty 36"</b>			
Deck .....	600726		6684BR
Hydro. Pump .....	788794		6943BR
<b>FasTrak Super Duty 42"</b>			
Deck .....	600734		6727BR
Hydro. Pump .....	788794		6943BR
<b>FasTrak Super Duty 48"</b>			
Eng. To Deck .....	791335		7057BR
Hydro. Pump .....	600979		6891BR
<b>FasTrak Super Duty 54"</b>			
Deck .....	789388		6732BR
Hydro. Pump .....	600979		6891BR
<b>FasTrak Super Duty 60"</b>			
Deck Drive .....	782292		6733BR
Hydro. Pump .....	600979		6891BR
<b>Hustler Mini Z 19/44</b>			
Deck Drive .....	791335		7057BR
<b>Hustler Mini Z 19/52</b>			
Deck Drive .....	789388		6732BR
<b>Hustler Mini Z 20/44</b>			
Deck Drive .....	791335		7057BR
<b>Hustler Mini Z 20/52; Hustler Mini Z 23/52; Hustler Mini Z 24/52</b>			
Deck Drive .....	789388		6732BR
<b>Hustler Sport 17.5/42</b>			
Deck Drive .....	600726		6684BR
Hydro. Pump .....	769133		6448BR
<b>Hustler Sport 21/48</b>			
Deck Drive .....	771634		6845BR
Hydro. Pump .....	769133		6448BR
<b>Hustler Super Z 24/60</b>			
Deck Drive; W/Side Discharge .....	781310		6844BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Super Z 24/72</b>			
Deck Drive; W/Side Discharge .....	784207		6803BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Super Z 25/60</b>			
Deck Drive; W/Side Discharge .....	781310		6844BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Super Z 25/72</b>			
Deck Drive; W/Side Discharge .....	784207		6803BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Super Z 26/66</b>			
Deck Drive .....	797936		6784BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Super Z 27/60</b>			
Deck Drive; W/Side Discharge; 2010 & Older .....	781310		6844BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSTLER EXCEL - Continued</b>			
<b>Hustler Super Z 27/60 – Continued</b>			
Deck Drive; W/Side Discharge; 2011 .....	602744		6919BR
Hydro. Pump; 2010 & Older .....	781443		6793BR
Hydro. Pump; 2011 .....	602762		6846BR
<b>Hustler Super Z 28/66; Hustler Super Z 30/66; Hustler Super Z 31/66</b>			
Deck Drive .....	797936		6784BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Z 23/52</b>			
Deck Drive .....	782292		6733BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Z 23/60; Hustler Z 24/60</b>			
Deck Drive .....	781310		6844BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Z 25/52</b>			
Deck Drive .....	782292		6733BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Z 25/60</b>			
Deck Drive .....	781310		6844BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Z 25/72</b>			
Deck Drive .....	784207		6803BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Z 27/52</b>			
Deck Drive .....	782292		6733BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Z 27/60</b>			
Deck Drive .....	781310		6844BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Z 27/72</b>			
Deck Drive .....	784207		6803BR
Hydro. Pump .....	781443		6793BR
<b>Hustler Z Diesel</b>			
Blade Drive; W/60" Deck; W/Rear Discharge; 2011 & Newer .....	603397		6942BR
Blade Drive; W/72" Deck; W/Rear Discharge; 2011 & Newer .....	603397		6942BR
Deck Drive; W/54" Deck; W/Side Discharge; 2010 & Older .....	601525		6882BR
Deck Drive; W/54" Deck; W/Side Discharge; 2011 & Newer .....	603687		6934BR
Eng. To Deck; W/60" Deck; W/Rear Discharge; 2011 & Newer .....	602854		6761BR
<b>Hustler Z XR-7 24/60; Hustler Z XR-7 25/60; Hustler Z XR-7 26/60; Hustler Z XR-7 27/60; Hustler Z XR-7 29/60</b>			
Deck Drive .....	797720		6802BR
Hydro. Pump .....	781443		6793BR
<b>Mini FasTrak 36"</b>			
Deck .....	793828		6848BR
Hydro. Pump .....	793836		6847BR
<b>Mini FasTrak 42"</b>			
Deck .....	793893		6486BR
Hydro. Pump .....	793836		6847BR
<b>Raptor 15/36</b>			
Deck Drive .....	771824		6923BR
<b>Raptor 21.5/42; Raptor 22/42</b>			
Deck Drive .....	793828		6848BR
<b>Raptor 23/52; Raptor 24/52</b>			
Deck Drive .....	791988		6906BR
<b>Raptor Flip-Up 25/48</b>			
Deck Drive .....	602078		6878BR
<b>Raptor Flip-Up 25/54</b>			
Deck Drive .....	797720		6802BR
<b>Raptor SD 22/36</b>			
Deck Drive .....	603806		7029BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSTLER EXCEL - Continued</b>			
<b>Raptor SD 22/42</b>			
Deck Drive .....	606016		7048BR
<b>Raptor SD 23/48</b>			
Deck Drive .....	604830		6785BR
<b>Raptor SD 24/60</b>			
Deck Drive .....	604711		6597BR
<b>Raptor SD 25/48</b>			
Deck Drive .....	604830		6785BR
<b>Raptor SD 26/60</b>			
Deck Drive .....	604711		6597BR
<b>Sport 15/42; Sport 16/42</b>			
Deck Drive .....	600726		6684BR
Hydro. Pump .....	769133		6448BR
<b>Sport 16/48; Sport 18/48</b>			
Deck Drive .....	771634		6845BR
Hydro. Pump .....	769133		6448BR
<b>Sport 21.5/54; Sport 26/54</b>			
Deck Drive .....	777185		6567BR
Hydro. Pump .....	769133		6448BR
<b>Super 104</b>			
Deck - Center .....	603786		6857BR
Deck - Left & Right .....	603885		6858BR
Hydro. Pump .....	603904		6502BR
<b>Super Mini Z 23/44</b>			
Deck Drive .....	791335		7057BR
<b>Super Mini Z 24/52; Super Mini Z 25/52</b>			
Deck Drive .....	789388		6732BR
<b>Super S 22/48</b>			
Deck Drive .....	601788		6646BR
<b>Super S 22/52; Super S 23/52</b>			
Deck Drive .....	786491		6566BR
<b>Super Z 27/54</b>			
Deck Drive .....	601715		6859BR
<b>Super Z 27/60</b>			
Deck Drive; W/Side Discharge; 2012 & Older .....	602744		6919BR
Eng. To Deck; W/Rear Discharge; 2012 & Older .....	789388		6732BR
Eng. To Deck; W/Rear Discharge; 2013 & Newer .....	777185		6567BR
Hydro. Pump; 2012 & Older .....	602762		6846BR
<b>Super Z 27/72</b>			
Deck Drive; W/Side Discharge; 2012 & Older .....	602747		6921BR
Deck Drive; W/Side Discharge; 2013 & Newer .....	784207		6803BR
Eng. To Deck; W/Rear Discharge; 2012 & Older .....	782292		6733BR
Eng. To Deck; W/Rear Discharge; 2013 & Newer .....	797928		6768BR
Hydro. Pump; 2012 & Older .....	602762		6846BR
<b>Super Z 29/54</b>			
Deck Drive .....	601715		6859BR
<b>Super Z 29/60</b>			
Deck Drive; W/Side Discharge .....	602744		6919BR
Hydro. Pump .....	602762		6846BR
<b>Super Z 29/66</b>			
Deck Drive; W/Side Discharge .....	602860		6920BR
Hydro. Pump .....	602762		6846BR
<b>Super Z 31/60</b>			
Deck Drive; W/Side Discharge .....	602744		6919BR
Hydro. Pump .....	602762		6846BR
<b>Super Z 31/72</b>			
Deck Drive; W/Side Discharge .....	602747		6921BR
Hydro. Pump .....	602762		6846BR
<b>Super Z 33/66</b>			
Deck Drive .....	602854		6761BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSTLER EXCEL - Continued</b>			
<b>Super Z 33/72</b>			
Deck Drive; W/Side Discharge .....	784207		6803BR
Eng. To Deck; W/Rear Discharge .....	797928		6768BR
<b>Super Z 35/60</b>			
Deck Drive; W/Side Discharge; 2012 & Older .....	602744		6919BR
Eng. To Deck; W/Rear Discharge .....	789388		6732BR
Hydro. Pump; 2012 & Older .....	602762		6846BR
<b>Super Z 35/66</b>			
Deck Drive; W/Side Discharge; 2012 & Older .....	602860		6920BR
Deck Drive; W/Side Discharge; 2013 & Newer .....	602854		6761BR
Hydro. Pump; 2012 & Older .....	602762		6846BR
<b>Super Z 35/72</b>			
Deck Drive; W/Side Discharge; 2012 & Older .....	602747		6921BR
Deck Drive; W/Side Discharge; 2013 & Newer .....	784207		6803BR
Eng. To Deck; W/Rear Discharge .....	782292		6733BR
Hydro. Pump; 2012 & Older .....	602762		6846BR
<b>Super Z 37/60</b>			
Deck Drive; W/Side Discharge .....	602744		6919BR
Hydro. Pump .....	602762		6846BR
<b>Super Z 37/66</b>			
Deck Drive; W/Side Discharge .....	602860		6920BR
Hydro. Pump .....	602762		6846BR
<b>Super Z 37/72</b>			
Deck Drive; W/Side Discharge .....	602747		6921BR
Hydro. Pump .....	602762		6846BR
<b>Super Z HD 35/60</b>			
Eng. To Deck; W/Rear Discharge .....	777185		6567BR
<b>Super Z HD 35/72</b>			
Deck Drive; W/Side Discharge .....	784207		6803BR
Eng. To Deck; W/Rear Discharge .....	797928		6768BR
<b>Super Z HD 36/60</b>			
Eng. To Deck; W/Rear Discharge .....	777185		6567BR
<b>Super Z HD 36/72</b>			
Deck Drive; W/Side Discharge .....	784207		6803BR
Eng. To Deck; W/Rear Discharge .....	797928		6768BR
<b>Super Z HD 37/60</b>			
Eng. To Deck; W/Rear Discharge .....	777185		6567BR
<b>Super Z HD 37/66</b>			
Deck Drive .....	602854		6761BR
<b>Super Z HD 37/72</b>			
Deck Drive; W/Side Discharge .....	784207		6803BR
Eng. To Deck; W/Rear Discharge .....	797928		6768BR
<b>Super Z HD 38/60</b>			
Eng. To Deck; W/Rear Discharge .....	777185		6567BR
<b>Super Z HD 38/72</b>			
Deck Drive; W/Side Discharge .....	784207		6803BR
Eng. To Deck; W/Rear Discharge .....	797928		6768BR
<b>X-One 22/48</b>			
Deck Drive; 2012 & Older .....	786483		6692BR
Deck Drive; 2013 & Newer .....	786491		6566BR
Hydro. Pump; 2012 & Older .....	602907		6736BR
Hydro. Pump; 2013 & Newer .....	604858		6697BR
<b>X-One 22/54</b>			
Hydro. Pump; 2012 & Older .....	602907		6736BR
Hydro. Pump; 2013 & Newer .....	604858		6697BR
<b>X-One 23.5/54</b>			
Deck Drive; W/Side Discharge; 2012 & Older .....	797928		6768BR
Deck Drive; W/Side Discharge; 2013 & Newer .....	789388		6732BR
Hydro. Pump; 2012 & Older .....	602907		6736BR
Hydro. Pump; 2013 & Newer .....	604858		6697BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSTLER EXCEL - Continued</b>			
<b>X-One 23.5/60</b>			
Blade Drive; W/Rear Discharge .....	603397		6942BR
Deck Drive; W/Side Discharge; 2013 & Newer .....	782292		6733BR
Eng. To Deck; W/Rear Discharge; 2012 & Older .....	777185		6567BR
Eng. To Deck; W/Rear Discharge; 2013 & Newer .....	784322		6779BR
Hydro. Pump; 2012 & Older .....	602907		6736BR
Hydro. Pump; 2013 & Newer .....	604858		6697BR
<b>X-One 24/48; X-One 25/48</b>			
Deck Drive .....	786483		6692BR
Hydro. Pump .....	602907		6736BR
<b>X-One 26/54</b>			
Deck Drive .....	797928		6768BR
Hydro. Pump .....	602907		6736BR
<b>X-One 26/60</b>			
Hydro. Pump .....	602907		6736BR
<b>X-One 27/54</b>			
Deck Drive; W/Side Discharge; 2012 & Older .....	797928		6768BR
Deck Drive; W/Side Discharge; 2013 & Newer .....	789388		6732BR
Hydro. Pump; 2012 & Older .....	602907		6736BR
Hydro. Pump; 2013 & Newer .....	604858		6697BR
<b>X-One 27/60</b>			
Deck Drive; W/Side Discharge; 2013 & Newer .....	782292		6733BR
Hydro. Pump; 2012 & Older .....	602907		6736BR
Hydro. Pump; 2013 & Newer .....	604858		6697BR
<b>X-One 28/54</b>			
Deck Drive; W/Side Discharge .....	789388		6732BR
Hydro. Pump .....	604858		6697BR
<b>X-One 28/60</b>			
Blade Drive; W/Rear Discharge .....	603397		6942BR
Deck Drive; W/Side Discharge .....	782292		6733BR
Eng. To Deck; W/Rear Discharge .....	784322		6779BR
Hydro. Pump .....	604858		6697BR
<b>X-One 29/60</b>			
Deck Drive .....	782292		6733BR
Hydro. Pump .....	602907		6736BR
<b>X-One 31/60</b>			
Hydro. Pump .....	602907		6736BR
<b>X-One i 22/52</b>			
Deck Drive .....	789388		6732BR
Hydro. Pump .....	788794		6943BR
<b>X-One i 23.5/60</b>			
Deck Drive .....	782292		6733BR
Hydro. Pump .....	788794		6943BR
<b>Z4</b>			
Deck Drive; W/48" Deck .....	786483		6692BR
Deck Drive; W/60" Deck .....	602078		6878BR
Pump Drive .....	601947		6735BR
<b>INGERSOLL</b>			
<b>80XC; 80XE; 80XI; 80XM</b>			
Eng. To Deck .....	C24342		6836
Traction .....	C24342		6836
<b>108YT</b>			
P.T.O. ....	C19171		6833
Trans.; Ser. No. 14084846 & Before .....	C29878		6880
Trans.; Ser. No. 14084847 & After .....	C29699		6884
<b>114YT</b>			
P.T.O. ....	C19171		6833
Trans.; Ser. No. 14087759 & Before .....	C29878		6880
Trans.; Ser. No. 14087760 & After .....	C29699		6884
<b>116YT</b>			
P.T.O. ....	C19171		6833
Trans.; Ser. No. 14089590 & Before .....	C29878		6880
Trans.; Ser. No. 14089591 & After .....	C29699		6884

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>INGERSOLL - Continued</b>			
<b>220; 222</b>			
Deck; W/G-40 Deck .....	C23810		6869
Deck; W/G-44 Deck .....	C22707		6876
Deck; W/G-46 Deck .....	C22708		6880
Deck; W/H-40 Deck .....	C23810		6869
Deck; W/H-44 Deck .....	C22707		6876
Deck; W/H-46 Deck .....	C22708		6880
Drive; W/G-40 Deck .....	C23805		6866
Drive; W/G-44 Deck .....	C23804		6867
Drive; W/G-46 Deck .....	C23804		6867
Drive; W/H-40 Deck .....	C23807		6864
Drive; W/H-44 Deck .....	C23807		6864
Drive; W/H-46 Deck .....	C23708		6864
<b>444</b>			
Deck; W/F-44 Deck .....	C23811		3V750
Deck; W/F-46 Deck .....	C22708		6880
Deck; W/G-44 Deck .....	C22707		6876
Deck; W/G-46 Deck .....	C22708		6880
Deck; W/H-40 Deck .....	C23810		6869
Deck; W/H-44 Deck .....	C22707		6876
Deck; W/H-46 Deck .....	C22708		6880
Deck; W/J-40, K-40 Deck .....	C23810		6869
Deck; W/J-44, J-45, K-44, K-45 Deck .....	C22707		6876
Deck; W/J-46, K-46 Deck .....	C22708		6880
Drive; W/F-46 Deck .....	C23810		6869
Drive; W/G-44 Deck .....	C23806		6870
Drive; W/G-46 Deck .....	C23806		6870
Drive; W/H-40 Deck .....	C23809		6870
Drive; W/H-44 Deck .....	C23809		6870
Drive; W/H-46 Deck .....	C23809		6870
Drive; W/J-40, K-40 Deck .....	C23359		6871
Drive; W/J-44, J-45, K-44, K-45 Deck .....	C23359		6871
Drive; W/J-46, K-46 Deck .....	C23359		6871
<b>446; 448</b>			
Deck; W/J-40, K-40 Deck .....	C23810		6869
Deck; W/J-44, J-45, K-44, K-45 Deck .....	C22707		6876
Deck; W/J-46, K-46 Deck .....	C22708		6880
Drive; W/J-40, K-40 Deck .....	C23359		6871
Drive; W/J-44, J-45, K-44, K-45 Deck .....	C23359		6871
Drive; W/J-46, K-46 Deck .....	C23359		6871
<b>808</b>			
Deck .....	C24349		6873
<b>810</b>			
Deck .....	305698		6873
<b>1112H</b>			
Deck .....			6978
<b>3010; 3012</b>			
Eng. To Deck .....	C23358		6750BR
<b>INTERNATIONAL</b>			
<b>Cadet 55</b>			
Blade .....	488077R1		6848
Forward .....	549108R1		6838
<b>Cadet 60</b>			
Blade .....	488077R1		6848
Forward .....	487994R1		6837
Mower .....	488082R1		6852
Reverse .....	487996R1		6835
<b>Cadet 70</b>			
Drive; W/36 5/8" Belt O.C. ....	214878R1	7360	
Drive; W/38", 42", 48" Deck .....	490489R2		6513BR
Gen. ....	376230R1		3V315
Hyd. Pump .....	386160R1	7330	
<b>Cadet 71</b>			
Drive .....	214878R1	7360	
Gen. ....	376230R1		3V315
Hyd. Pump .....	386160R1	7330	
<b>Cadet 72</b>			
Drive .....	214878R1	7360	
Gen. ....	401960R1	7320	
<b>Cadet 73</b>			
Gen. ....	401960R1	7320	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>INTERNATIONAL - Continued</b>			
<b>Cadet 76</b>			
Clutch .....	549821R1		6831
Drive .....	549822R1		6868
<b>Cadet 80</b>			
Clutch .....	61083C1		6832
Drive .....	56235C1		6868
<b>Cadet 81</b>			
Drive .....	56235C1		6868
<b>Cadet 86</b>			
Drive; W/38", 42", 48" Deck .....	490489R2		6513BR
Gen. ....	401960R1	7320	
<b>Cadet 100; Cadet 102; Cadet 104; Cadet 105; Cadet 106; Cadet 107; Cadet 108; Cadet 109; Cadet 122</b>			
Gen. ....	376230R1		3V315
Hyd. Pump .....	386160R1	7330	
<b>Cadet 123</b>			
Drive; W/38", 42", 48" Deck .....	490489R2		6513BR
Gen. ....	376230R1		3V315
Hyd. Pump .....	386160R1	7330	
<b>Cadet 124; Cadet 125; Cadet 126; Cadet 127; Cadet 128; Cadet 129</b>			
Gen. ....	376230R1		3V315
Hyd. Pump .....	386160R1	7330	
<b>Cadet 147; Cadet 149</b>			
Gen. ....	401960R1	7320	
Hyd. Pump .....	386160R1	7330	
<b>Cadet 169</b>			
Drive; W/38", 42", 48" Deck .....	490489R2		3V800
Gen. ....	401960R1	7320	
Hyd. Pump .....	386160R1	7330	
<b>Cadet 182</b>			
Eng. To Deck .....	132407C1		6869
Eng. To J.S. ....	132013C1		6830
J.S. To Trans. ....	549822R1		6868
<b>Cadet 282</b>			
Eng. To Deck .....	132407C1		6869
Eng. To J.S. ....	61083C1		6832
J.S. To Trans. ....	61084C1		6859
<b>Cadet 382</b>			
Eng. To Deck .....	132407C1		6869
Eng. To J.S. ....	132013C1		6830
J.S. To Trans. ....	549822R1		6868
<b>Cadet 482</b>			
Trans. ....	126496C1		6833
<b>Cadet 982</b>			
P.T.O. ....	140080C1		6832
<b>Cub</b>			
Drive .....	376230R1		3V315
Fan .....	251428R1		TR24315
<b>Cub Lo Boy 154; Cub Lo Boy 184; Cub Lo Boy 185</b>			
Fan & Gen. ....	527621R1	7480	
<b>J.C. PENNEY CO.</b>			
<b>850-5992</b>			
Cross Deck .....	37X66		6475BR
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
<b>870-0742</b>			
Cross Deck .....	37X66		6475BR
Deck; Model No. 44620X25B .....	37X70		6603BR
Drive .....	37X61		6452BR
<b>JACOBSEN</b>			
<b>70" Trimmer</b>			
Eng. To Hydro. ....	336263		6825
P.T.O. ....	336262		6832



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JACOBSEN - Continued</b>			
<b>110</b>			
Intermediate Pulley To J.S. ....	336219		6830
Mower Deck .....	390008		6847
<b>1200</b>			
Drive .....	330559		6946
<b>1650</b>			
P.T.O. To Deck .....	328892		6883
<b>1962</b>			
Hyd. Pump; W/Diesel Eng. ....	3001869		6944
Hyd. Pump; W/Gas Eng. ....	336481		6943
<b>42602</b>			
Blade .....	311496		6857
Differential .....	311419	2280	6828
Gen. ....	312529	1240	6724
<b>42620; 42622; 42625; 42627</b>			
Blade .....	331846	2510	6851
Traction .....	331672	2480	6848
<b>42635</b>			
Blade .....	546343		6852
Eng. To Variator .....	546341		6925
Variator .....	546342		6931
<b>42636; 42638; 42641; 42642; 42650; 42651</b>			
Drive .....	330463		6876
<b>43002</b>			
Blade .....	331847		6848
Traction .....	331672	2480	6848
<b>43026; 43027; 43029; 43031; 43032; 43034;</b>			
<b>43036; 43037; 43042; 43043</b>			
Drive .....	330463		6876
<b>53028; 53032</b>			
Gen. ....	315402		6832
Trans. ....			6978
<b>53033; 53034</b>			
Gen.; W/32" Belt O.C. ....	315402		6832
Gen.; W/35" Belt O.C. ....	326227	7350	
Trans. ....	342660		6977
<b>53035; 53036; 53037; 53038; 53039; 53050</b>			
Gen. ....	326227	7350	
Trans. ....	342660		6977
<b>53070</b>			
Gen. ....	315402		6832
<b>53074</b>			
Gen.; W/32" Belt O.C. ....	315402		6832
Gen.; W/35" Belt O.C. ....	326227	7350	
Trans. ....	342660		6977
<b>53077</b>			
Gen. ....	326227	7350	
Trans. ....	342660		6977
<b>53080; 53082</b>			
Gen. ....	326227	7350	
Trans. ....	343359		6972
<b>53088</b>			
Gen. ....	326227	7350	
Trans. ....	342660		6977
<b>53090; 53092</b>			
Gen. ....	326227	7350	
Trans. ....	343359		6972
<b>53100; 53101; 53105; 53106; 53107; 53108</b>			
P.T.O. ....	332051		6829
Traction .....	329184	2840	6884
<b>53130</b>			
P.T.O. ....	332051		6829
Traction .....	328825		6884
<b>53132</b>			
P.T.O. ....	332051		6829

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JACOBSEN - Continued</b>			
<b>53145; 53146</b>			
P.T.O. ....	332051		6829
Trans. ....	329184	2840	6884
<b>53147</b>			
Blade .....	329193		6890
Eng. To J.S. ....	332051		6829
J.S. To Trans. ....	329184	2840	6884
<b>53148</b>			
Blade .....	328821		6883
Deck .....	390008		6847
Eng. To J.S. ....	336219		6830
J.S. To Trans. ....	329184	2840	6884
<b>53151</b>			
P.T.O. ....	329184		6830
Trans. ....	329184	2840	6884
<b>53200; 53215</b>			
Gen. ....	326227	7350	
<b>53245; 53259; 53260</b>			
Gen. ....	326227	7350	
Trans. ....	343359		6972
<b>233431</b>			
Belt; W/33" Belt O.C. ....	325984		6933
Front Reel .....	314600		6966
P.T.O. ....	325983	3280	
<b>1240287</b>			
Eng. To Deck; W/14 H.P. Eng. ....	JA992251		6864
<b>1240670</b>			
Eng. To Deck; W/18 H.P. Eng. ....	JA992251		6864
<b>Chief LT</b>			
Belt; W/29" Belt O.C. ....	332051		6829
Belt; W/30" Belt O.C. ....	336219		6830
Blade; W/82" Belt O.C.; W/42" Rotary Mower .....	328821		6882
Blade; W/83" Belt O.C.; W/42" Rotary Mower .....	328892		6883
Drive; W/34" Rotary Mower .....	329193		6890
Drive; W/42" Rotary Mower .....	390008		6847
Drive; W/45" Belt O.C. ....	329205		6845
P.T.O. ....	390188		6844
Traction .....	330447		6867
<b>Commercial 60"</b>			
Eng. To Hyd. Pump .....	333719		6962
<b>Commercial 72"</b>			
Eng. To Hyd. Pump .....	333719		6962
P.T.O. ....	336488		6943
Traction .....	336481		6943
<b>G-4X4</b>			
Fan & Alt. ....	REM1415	7420	
P.T.O. ....		9525	9525HD
<b>G-20D</b>			
Fan & Alt. ....	1687531M1	9525	9525HD
<b>G-Plex III</b>			
Blade Drive .....	365235		6678BR
<b>G-Plex III Diesel</b>			
Fan .....	5001951	7345	
<b>Greens King</b>			
Blade Drive .....	365235		6678BR
Hyd. Pump .....	332111		6844
<b>Greens King IV Plus Diesel</b>			
Fan .....	5001951	7345	
<b>GT</b>			
Auger .....	392410		6841
Blade; W/50" Rotary Mower .....	330503		6897
Blade; W/60" Rotary Mower .....	392397		B112
Drive; W/35 1/2" Belt O.C. ....	326227		3V355
Drive; W/35" Belt O.C. ....	330599		6835
Mower; W/50" Rotary Mower .....	328892		6883
Trans. ....	330559		6946

Lawn & Garden Equipment





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JACOBSEN - Continued</b>			
<b>HF-5D</b>			
W.P., Idler & J.S. ....	337854	7450	
<b>HF-15</b>			
Fan & Alt. ....	390324	9545	9545HD
<b>Hustler 400</b>			
Fan & Alt. ....	039289	7340	
Gov. ....	039271	7417	
<b>Hydro Turf King</b>			
Axle ....	330790		6836
Clutch; W/26" Belt O.C. ....	311649	3260	6926
Clutch; W/28" Belt O.C. ....	325983	3280	
Drive ....	314600		6966
Gen. ....	326227		3V355
Hydro. ....	335856		6839
Trans. ....	325984		6933
<b>Javelin 26"</b>			
Differential ....	311419		6828
Starter ....	312529		6724
<b>Javelin Mark II; Javelin Mark III</b>			
Drive ....	330463		6876
<b>JR830; JR1030E; JR1230E</b>			
Deck ....	JA991488		6873
Drive ....	JA990738		6852
<b>LF100</b>			
Fan & W.P. ....	337442	7430	
<b>LF128</b>			
Alt. & W.P. ....		7375	
<b>LF3810</b>			
Alt. ....		7385	
<b>Mowmobile 48"</b>			
Blade To Blade ....	310538	3360	6936
Eng. ....	311649	3260	6926
Gen. ....	310917	2350	6835
Idler ....	311650		6933
<b>Olympia; Olympic</b>			
Blade; W/48" Belt O.C. ....	331847	2480	6848
Blade; W/51" Belt O.C. ....	331846	2510	6851
Brake ....	331984	2160	
Traction ....	331672	2480	6848
<b>ST5111</b>			
Fan & Alt. ....	REMF6415	9425	9425HD
<b>T428D</b>			
Alt. & W.P. ....	JB-306-A	7300	
<b>T445G</b>			
Alt. & W.P. ....		7375	
<b>Turf Blazer 422</b>			
Fan & Alt. ....		7355	
<b>Turf Groomer</b>			
Auger ....	327161		C85
<b>Turf King</b>			
Axle ....	330790		6836
Clutch; W/26" Belt O.C. ....	311649	3260	6926
Clutch; W/28" Belt O.C. ....	325983	3280	
Drive ....	314600		6966
Gen. ....	326227		3V355
Hydro. ....	335856		6839
Trans. ....	325984		6933
<b>Turf King 76"</b>			
Axle; Late ....	330790		6836
Countershaft; Early ....	312571	3290	6929
Countershaft; W/29" Belt O.C.; Late ....	312571	3290	6929
Countershaft; W/66" Belt O.C.; Late ....	314600		6966
Differential; Late ....	325984	3330	6933
Differential; W/32" Belt O.C.; Early ....	312795		6932
Differential; W/33" Belt O.C.; Early ....	311650		6933
Eng.; Late ....	311649	3260	6926
Eng.; W/25" Belt O.C.; Early ....	312796		6925
Eng.; W/26" Belt O.C.; Early ....	311649	3260	6926

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JACOBSEN - Continued</b>			
<b>Turf King 76" - Continued</b>			
Gen.; Late ....	326227		3V355
Hydro.; Late ....	335856		6839
Reel Drive; Late ....	335832		6838
<b>Turf King 84"</b>			
Axle ....	330790		6836
Countershaft; W/29" Belt O.C. ....	312571	3290	6929
Countershaft; W/66" Belt O.C. ....	314600		6966
Differential ....	325984	3330	6933
Eng. ....	311649	3260	6926
Gen. ....	326227		3V355
Hydro. ....	335856		6839
Reel Drive ....	335832		6838
<b>UT32017; UT32020; UT32021; UT32022</b>			
Deck ....	JA991488		6873
Drive ....	JA990738		6852
<b>YT14; YT15; YT16; YT18</b>			
Eng. To Deck ....	JA992251		6864
<b>JARI</b>			
<b>N Poweride</b>			
Eng. To J.S. ....	N1133	3580	6958
<b>JOHN DEERE</b>			
<b>55 Riding Mower; 56</b>			
Blade ....	M44498		6860
Traction ....	M44483		6848
<b>57</b>			
Blade ....	M45863		6856
Deck ....	M45862		6847
Traction ....	M44483		6848
<b>60 Lawn Tractor</b>			
Primary ....	M43489		6857
Secondary ....	M41592		6840
<b>65 Lawn Tractor</b>			
Blade ....	M44498		6860
Traction ....	M44483		6848
<b>66</b>			
Blade ....	M80386		6864
Traction ....	M82167		6851
<b>68</b>			
Blade ....	M49920		6899
Traction ....	M82167		6851
<b>70 Lawn Tractor</b>			
Primary ....	M43489		6857
Secondary ....	M41592		6840
<b>85-086</b>			
Primary; W/11 H.P. Eng. ....	M89112		6463BR
<b>90; 96</b>			
Drive; Ser. No. 10000 & Before ....	M46758		6836
Drive; W/Electric Start; Ser. No. 10001 & After ....	M41592		6840
Drive; W/O Electric Start; Ser. No. 10001 & After ....			6840
<b>100</b>			
Primary ....	M43489		6857
Secondary ....	M41592		6840
<b>102</b>			
Deck Drive ....	GX20072		6651BR
Traction ....	GX22036		6757BR
<b>108</b>			
Drive ....	M83837		6463BR
Primary J.S.; W/970 Deck ....	M88184		6735BR
Secondary J.S.; W/762, 970 Deck; W/66" Belt O.C. ....	M82462		6743BR
Spindle; W/762 Deck; W/39" Belt O.C. ....	M82461		6839
<b>110</b>			
Blade To Blade; W/38", 39", 47" Deck ...	M40223		6532BR
Gen.; Ser. No. 100000 & Before ....	M41335		6732
Hyd.; Ser. No. 100000 & Before ....	M41341	7330	





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>110 – Continued</b>			
Primary; Ser. No. 100000 & Before .....	M40015		6935
Primary; Ser. No. 100001 & After .....	M82258		6940
Pump Drive; Ser. No. 100001 Thru 250000; W/Kohler Eng. ....	M44113	7419	
Pump Drive; Ser. No. 100001 Thru 250000; W/Tecumseh Eng. ....	M43106	7390	
Secondary; Ser. No. 100,000 & Before ..	M77988		7097BR
Secondary; Ser. No. 100000 & Before ...	M44121		6502BR
Secondary; Ser. No. 100001 & After .....	M44121		6502BR
<b>110H</b>			
Gen.; Ser. No. 100000 & Before .....	M41335		6732
Hyd.; Ser. No. 100000 & Before .....	M41341	7330	
Primary; Ser. No. 100000 & Before .....	M40015		6935
Primary; Ser. No. 100001 & After .....	M82258		6940
Pump Drive; Ser. No. 100001 Thru 250000; W/Kohler Eng. ....	M44113	7419	
Pump Drive; Ser. No. 100001 Thru 250000; W/Tecumseh Eng. ....	M43106	7390	
Secondary; Ser. No. 100,000 & Before ..	M77988		7097BR
Secondary; Ser. No. 100000 & Before ...	M44121		6502BR
Secondary; Ser. No. 100001 & After .....	M44121		6502BR
<b>111</b>			
Drive .....	M83837		6463BR
Primary J.S.; W/970 Deck .....	M88184		6735BR
Secondary J.S.; W/762, 970 Deck; W/66" Belt O.C. ....	M82462		6743BR
Spindle; W/762 Deck; W/39" Belt O.C. ...	M82461		6839
<b>111H</b>			
Drive .....	M84075		6672BR
P.T.O. ....	M82362		6463BR
Primary J.S.; W/970 Deck .....	M88184		6735BR
Secondary J.S.; W/762, 970 Deck; W/66" Belt O.C. ....	M82462		6743BR
Spindle; W/762 Deck; W/39" Belt O.C. ...	M82461		6839
<b>112</b>			
Blade To Blade; W/38", 39", 47" Deck ...	M40223		6532BR
Gen.; Ser. No. 100000 & Before .....	M41335		6732
P.T.O.; Ser. No. 100000 & Before .....	M40757		6877
Primary; Ser. No. 100001 & After .....	M82258		6940
Pump Drive; Ser. No. 100001 Thru 250000; W/Kohler Eng. ....	M44113	7419	
Pump Drive; Ser. No. 100001 Thru 250000; W/Tecumseh Eng. ....	M43106	7390	
Secondary; Ser. No. 100000 & Before ...	M77988		7097BR
Secondary; Ser. No. 100001 & After .....	M44121		6502BR
<b>112H</b>			
Gen.; Ser. No. 100000 & Before .....	M41335		6732
P.T.O.; Ser. No. 100000 & Before .....	M40757		6877
Primary; Ser. No. 100001 & After .....	M82258		6940
Pump Drive; Ser. No. 100001 Thru 250000; W/Kohler Eng. ....	M44113	7419	
Pump Drive; Ser. No. 100001 Thru 250000; W/Tecumseh Eng. ....	M43106	7390	
Secondary; Ser. No. 100001 & After .....	M44121		6502BR
Secondary; W/46" Deck .....	M77988		7097BR
<b>112L</b>			
Drive .....			6879
Primary; W/970 Deck .....	M77988		7097BR
Primary J.S.; W/970 Deck .....	M82734		6834
Secondary J.S.; W/970 Deck .....	M82462		6743BR
<b>115</b>			
Deck Drive .....	GX20072		6651BR
Traction .....	GX20006		6690BR
<b>116</b>			
Drive; Ser. No. 285000 & Before .....	M83837		6463BR
Drive; Ser. No. 285001 & After .....	M86996		6887
Primary; W/1170 Deck; W/62" Belt O.C. ....	M84223		6862
Primary; W/970 Deck; W/59" Belt O.C. ...	M84365		6859
Primary; W/970 Deck; W/60" Belt O.C. ...	M88184		6735BR
Secondary; W/1170 Deck; W/102" Belt O.C. ....	M84136		7015BR
Secondary; W/970 Deck; W/66" Belt O.C. ....	M82462		6743BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>116H</b>			
Drive .....	M84075		6672BR
Primary; W/1170 Deck; W/62" Belt O.C. ....	M84223		6862
Primary; W/970 Deck; W/59" Belt O.C. ...	M84365		6859
Primary; W/970 Deck; W/60" Belt O.C. ...	M88184		6735BR
Secondary; W/1170 Deck; W/102" Belt O.C. ....	M84136		7015BR
Secondary; W/970 Deck; W/66" Belt O.C. ....	M82462		6743BR
<b>120</b>			
Belt; W/41" Deck .....	M40757		6877
Belt; W/48" Deck .....	M41668		6533BR
Deck Drive; W/48" Deck .....	M82718		6713BR
P.T.O.; W/35" Belt O.C. ....	AM32172		6835
P.T.O.; W/36" Belt O.C. ....	AM32636		6836
P.T.O.; W/41" Belt O.C. ....	M43795		6841
Primary; W/83" Belt O.C. ....	M45998		6883
Primary; W/86" Belt O.C. ....	M45254		6886
<b>125 Riding Mower</b>			
Deck Drive .....	GX20072		6651BR
Traction .....	GX20006		6690BR
<b>130</b>			
Eng. To Blade .....	M90958		6855
Eng. To Trans. ....	M40757		6877
Traction .....	M86996		6887
<b>135</b>			
Deck Drive .....	GX20072		6651BR
Traction .....	GX20006		6690BR
<b>140</b>			
Belt; W/41" Deck .....	M40757		6877
Belt; W/48" Deck .....	M41668		6533BR
Deck Drive; W/48" Deck .....	M82718		6713BR
P.T.O.; W/35" Belt O.C. ....	AM32172		6835
P.T.O.; W/36" Belt O.C. ....	AM32636		6836
P.T.O.; W/41" Belt O.C. ....	M43795		6841
Primary; W/83" Belt O.C. ....	M45998		6883
Primary; W/86" Belt O.C. ....	M45254		6886
<b>145; 155C</b>			
Deck Drive; W/48" Deck .....	GX21833		6686BR
Traction .....	GX20006		6690BR
<b>160</b>			
Blade; W/38" Deck .....	M82462		6743BR
Blade; W/46" Deck .....	M84136		7015BR
Drive; W/38" Deck .....	M82734		6860
Drive; W/46" Deck .....	M91147		6863
Eng. To J.S. ....	M91147		6863
Primary .....	M77988		7097BR
Trans. ....	M83837		6463BR
<b>165</b>			
Primary; W/970 38" Deck; Ser. No. 420001 & After .....	M82734		6860
Primary; W/970 38" Deck; W/60" Belt O.C. ....	M82734		6860
Secondary; W/970 38" Deck; Ser. No. 420001 & After .....	M82462		6866
Secondary; W/970 38" Deck; W/66" Belt O.C. ....	M82462		6743BR
Traction; W/79" Belt O.C. ....	M84075		6672BR
Traction; W/87" Belt O.C.; Ser. No. 420001 & After .....	M86996		6887
<b>170 Riding Mower</b>			
Primary; W/38" Deck; Ser. No. 420001 & After .....	M77988		7097BR
Primary; W/46" Deck .....	M91147		6863
Secondary; W/38" Deck .....	M82462		6743BR
Secondary; W/46" Deck .....	M84136		7015BR
Trans. ....	M86996		6627BR
<b>175</b>			
Primary; W/1170 Deck .....	M91147		6863
Primary; W/970 Deck; W/60" Belt O.C. ...	M82734		6860
Primary; W/970 Deck; W/61" Belt O.C. ...	M77988		7097BR
Primary; W/970 Deck; W/80" Belt O.C. ...	M73223		6880
Secondary; W/1170 Deck .....	M84136		7015BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>175 - Continued</b>			
Secondary; W/970 Deck; W/66" Belt O.C. ....	M82462		6743BR
Traction; Ser. No. 475000 & Before .....	M89832		6637BR
Traction; Ser. No. 475001 & After .....	M73223		6880
Traction; W/78 1/2" Belt O.C. ....	M84075		6672BR
Trans. ....	M86996		6887
<b>180</b>			
Primary; W/38" Deck .....	M77988		7097BR
Primary; W/46" Deck .....	M91147		6863
Secondary; W/38" Deck .....	M82462		6743BR
Secondary; W/46" Deck .....	M84136		7015BR
Trans. ....	M86996		6627BR
<b>185</b>			
Drive; W/78 1/2" Belt O.C. ....	M84075		6672BR
Drive; W/79 1/3" Belt O.C. ....	M89832		6637BR
Primary; W/38" Deck .....	M77988		7097BR
Primary; W/46" Deck .....	M91147		6863
Secondary; W/38" Deck .....	M82462		6743BR
Secondary; W/46" Deck .....	M84136		7015BR
<b>190C</b>			
Deck Drive .....	GX21395		6769BR
Traction .....	GX21986		6627BR
<b>200</b>			
Hyd. Pump .....	M48520		6825
Primary .....	M47766		6508BR
Traction; W/40" Belt O.C. ....	M82258		6940
Traction; W/68" Belt O.C. ....	M44121		6502BR
Traction; W/74" Belt O.C. ....	M43820		6914BR
<b>208</b>			
Primary .....	M47766		6508BR
Traction; W/40" Belt O.C. ....	M82258		6940
Traction; W/68" Belt O.C. ....	M44121		6502BR
Traction; W/74" Belt O.C. ....	M43820		6914BR
<b>210; 212; 214</b>			
Hyd. Pump .....	M48520		6825
Primary .....	M47766		6508BR
Traction; W/40" Belt O.C. ....	M82258		6940
Traction; W/68" Belt O.C. ....	M44121		6502BR
Traction; W/74" Belt O.C. ....	M43820		6914BR
<b>216</b>			
Hyd. Pump .....	M48520		6825
Primary .....	M47766		6508BR
Tiller Attachment .....	M81805		6849
Traction; W/40" Belt O.C. ....	M82258		6940
Traction; W/68" Belt O.C. ....	M44121		6502BR
Traction; W/74" Belt O.C. ....	M43820		6914BR
<b>240; 245; 260</b>			
Primary; W/38" Deck .....	M73478		6859
Primary; W/46" Deck .....	M84223		6862
Primary; W/48" Deck .....	M77988		7097BR
Secondary; W/38" Deck .....	M82462		6743BR
Secondary; W/46" Deck .....	M84136		7015BR
Secondary; W/48" Deck .....	M110313		6650BR
Traction; W/74" Belt O.C. ....	M71135		6874
Traction; W/84" Belt O.C. ....	M71026		6884
<b>265</b>			
Primary; W/46" Deck .....	M84223		6862
Primary; W/48" Deck .....	M77988		7097BR
Secondary; W/46" Deck .....	M84136		7015BR
Secondary; W/48" Deck .....	M110313		6650BR
Traction .....	M71135		6874
<b>285</b>			
Primary; W/46" Deck; Ser. No. 010417 & Before .....	M84223		6862
Primary; W/46" Deck; Ser. No. 010418 & After .....	M95861		6861
Primary; W/48" Deck .....	M77988		7097BR
Primary; W/50" Deck .....	M84223		6862
Secondary; W/46" Deck .....	M84136		7015BR
Secondary; W/48" Deck .....	M110313		6650BR
Traction .....	M71135		6874

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>300 Hydro</b>			
Deck Drive .....	M82718		6713BR
P.T.O. ....	M43795		6841
<b>312; 314</b>			
Deck Drive; W/48" Deck .....	M82718		6713BR
P.T.O. ....	M43795		6841
<b>316</b>			
Deck Drive; W/48" Deck; Ser. No. 095000 & Before .....	M82718		6713BR
Deck Drive; W/48" Deck; Ser. No. 285001 & After .....	M119872		6710BR
P.T.O.; Ser. No. 095000 & Before .....	M43795		6841
P.T.O.; Ser. No. 285001 & After .....	M86060		6843
Primary .....	M89090		5701
<b>317</b>			
Deck Drive; W/48" Deck; Ser. No. 095000 & Before .....	M82718		6713BR
Deck Drive; W/48" Deck; Ser. No. 095001 & After .....	M119872		6710BR
P.T.O. ....	M82720		6845
<b>318</b>			
Belt; W/98" Belt O.C. ....	M41668		6533BR
Deck Drive; W/48" Deck; Ser. No. 095000 & Before .....	M82718		6713BR
Deck Drive; W/48" Deck; Ser. No. 285001 & After .....	M119872		6710BR
P.T.O.; W/43" Belt O.C. ....	M86060		6843
P.T.O.; W/90" Belt O.C. ....	M82718		6713BR
Primary .....	M89090		5701
<b>320 Lawn Tractor</b>			
Primary; W/48" Deck .....	M77988		7097BR
Secondary; W/48" Deck .....	M110313		6650BR
Snow Thrower Attachment .....	PT2303		6737
Traction .....	M71135		6874
<b>322</b>			
Blade To Blade .....	M119685		B101
Drive .....	M119871		6524BR
Fan; W/34 5/8" Belt O.C. ....	M800048	7340	
Fan; W/36 5/8" Belt O.C. ....	M1900T	7360	
Gen. ....	M1862T	7250	
Primary; W/107" Belt O.C. ....	M89111		68107
Primary; W/108" Belt O.C. ....	M71730		6379
<b>325</b>			
Primary; W/38" Deck .....	M117608		6915BR
Primary; W/44" Deck .....	M119696		6863BR
Primary; W/48" Deck .....	M143019		6655BR
Primary; W/54" Deck .....	M143019		6655BR
Secondary; W/38" Deck .....	M82462		6743BR
Secondary; W/44" Deck .....	M115776		6805BR
Secondary; W/48" Deck .....	M154958		6650BR
Secondary; W/54" Deck .....	M118685		6843BR
Traction; Ser. No. 070000 & Before .....	M118048		6866BR
<b>330 Lawn Tractor</b>			
Blade To Blade .....	M119685		B101
Drive .....	M119871		6524BR
Fan; W/34 5/8" Belt O.C. ....	M800048	7340	
Fan; W/36 5/8" Belt O.C. ....	M1900T	7360	
Gen. ....	M1862T	7250	
Primary; W/107" Belt O.C. ....	M89111		68107
Primary; W/108" Belt O.C. ....	M71730		6379
<b>332</b>			
Fan; W/34 5/8" Belt O.C. ....	M800048	7340	
Fan; W/36 5/8" Belt O.C. ....	M1900T	7360	
Gen. ....	M1862T	7250	
Primary; W/48" Deck .....	M119871		6524BR
Primary; W/50" Deck .....	M89112		6463BR
Secondary; W/48" Deck .....	M119685		B101
Secondary; W/50" Deck .....	M41668		6533BR
<b>345</b>			
Primary; W/38" Deck .....	M117608		6915BR
Primary; W/44" Deck .....	M119696		6863BR
Primary; W/48" Deck .....	M143019		6655BR
Primary; W/54" Deck .....	M143019		6655BR
Secondary; W/38" Deck .....	M82462		6743BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>345 - Continued</b>			
Secondary; W/44" Deck	M115776		6805BR
Secondary; W/48" Deck	M154958		6650BR
Secondary; W/54" Deck	M118685		6843BR
Traction; Ser. No. 070000 & Before	M118048		6866BR
<b>355D</b>			
Deck Drive; W/54" Deck	M112269		6724BR
Primary; W/38" Deck	M117608		6915BR
Primary; W/44" Deck	M119639		6863BR
Primary; W/48" Deck	M143019		6655BR
Secondary; W/38" Deck	M82462		6743BR
Secondary; W/44" Deck	M115776		6805BR
Secondary; W/48" Deck	M154958		6650BR
<b>400 Hydro</b>			
P.T.O.	AM35380		6841
<b>415</b>			
Fan	M800048	7340	
<b>420 Lawn Tractor</b>			
Fan	M3055T		TR22358
Gen.	M1862T	7250	
P.S.; Ser. No. 131818 Thru 158074	T10552T	7312	
P.S.; Ser. No. 158075 & After	T12267T	7335	
P.T.O.	AM35380		6841
<b>425 Lawn Tractor</b>			
Deck Drive; W/48" Deck	M112268		6694BR
Deck Drive; W/54" Deck	M112269		6724BR
Deck Drive; W/60" Deck	M120381		6695BR
Fan	M97340		6733
P.T.O.	AM35380		6841
<b>430 Lawn Tractor</b>			
Fan	M3055T		TR22358
Gen.	M1862T	7250	
P.S.; Ser. No. 131818 Thru 158074	T10552T	7312	
P.S.; Ser. No. 158075 & After	T12267T	7335	
P.T.O.	AM35380		6841
<b>445</b>			
Deck Drive; W/48" Deck	M112268		6694BR
Deck Drive; W/54" Deck	M112269		6724BR
Deck Drive; W/60" Deck	M120381		6695BR
Fan	M97340		6733
P.T.O.	AM35380		6841
<b>455</b>			
Deck Drive; W/48" Deck	M112268		6694BR
Deck Drive; W/54" Deck	M112269		6724BR
Deck Drive; W/60" Deck	M120381		6695BR
Fan	M97340		6733
P.T.O.	AM35380		6841
W.P.	M800347	7360	
<b>524</b>			
Auger	PT9739		6841
Forward	M81036		6833
Reverse	M81037		6832
Traction	PT9738		6731
<b>636M</b>			
Deck Drive; Ser. No. 045000 & Before	TCU37206		6838BR
Hydro. Drive	TCU37189		6819BR
<b>647A</b>			
Deck Drive; Ser. No. 030000 & Before	TCU17497		6589BR
<b>648M</b>			
Blade Drive	TCU34217		6822BR
Eng. To Deck; Ser. No. 045000 & Before	TCU37206		6838BR
Hydro. Drive	TCU37189		6819BR
<b>648R</b>			
Blade Drive	TCU34217		6822BR
Eng. To Deck; Ser. No. 045000 & Before	TCU34229		6840BR
Eng. To Deck; Ser. No. 045001 & After	UC11267		6555BR
Hydro. Drive	TCU34214		6837BR
<b>652B</b>			
Blade Drive	TCU34215		6823BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>652B - Continued</b>			
Eng. To Deck; Ser. No. 045000 & Before	TCU34219		6866BR
Eng. To Deck; Ser. No. 045001 & After	UC11266		6754BR
Hydro. Drive	TCU34214		6837BR
<b>652E</b>			
Blade Drive	TCU34215		6823BR
Eng. To Deck	UC11266		6754BR
Hydro. Drive	TCU34214		6837BR
<b>652M</b>			
Blade Drive	TCU34215		6823BR
Eng. To Deck; Ser. No. 045000 & Before	TCU37207		6675BR
Hydro. Drive	TCU37189		6819BR
<b>652R</b>			
Blade Drive	TCU34215		6823BR
Eng. To Deck; Ser. No. 045000 & Before	TCU34219		6866BR
Eng. To Deck; Ser. No. 045001 & After	UC11266		6754BR
Hydro. Drive	TCU34214		6837BR
<b>657A</b>			
Deck Drive; Ser. No. 030000 & Before	TCU18117		6596BR
Deck Drive; Ser. No. 030001 Thru 070000	TCU19456		6786BR
Deck Drive; Ser. No. 070001 & After	TCU29856		6845BR
<b>661R</b>			
Blade Drive	TCU34216		6855BR
Eng. To Deck; Ser. No. 045000 & Before	TCU34218		6856BR
Eng. To Deck; Ser. No. 045001 & After	UC11303		6806BR
Hydro. Drive	TCU34214		6837BR
<b>667A</b>			
Deck Drive; Ser. No. 030000 & Before	TCU18602		6692BR
Deck Drive; Ser. No. 030001 & After	TCU14356		6787BR
<b>717A</b>			
Blower	TCU21814		6691BR
Deck Drive	TCU18602		6692BR
Hydro.	TCU20002		6697BR
<b>727A</b>			
Blower	TCU21814		6691BR
Deck Drive	TCU18603		6997BR
Hydro.	TCU20002		6697BR
<b>737; 757</b>			
Deck Drive; W/54" Deck	TCU13196		6946BR
Deck Drive; W/60" Deck	TCU13198		6616BR
Hydro. Pump; Ser. No. 030000 & Before	TCU12829	K060620	
Hydro. Pump; Ser. No. 030001 & After	TCU16026		6929BR
Mule Drive; Ser. No. 030001 & After	TCU16907		6665BR
Mule Drive; Ser. No. 30000 & Before	TCU13195		6688BR
<b>777; 797</b>			
Deck Drive; W/60" Deck	TCU13198		6616BR
Deck Drive; W/72" Deck	TCU16036		6762BR
Eng. Fan	M147344	7335	
Hydro. Drive; Ser. No. 020000 & Before	TCU16841		6699BR
Hydro. Drive; Ser. No. 020001 & After	TCU16026		6929BR
Mule Drive	TCU16495		6867BR
<b>997 Z-TRAK Diesel</b>			
Deck Drive; W/60" Deck; Ser. No. 055000 & Before	DMU210479		7109BR
Deck Drive; W/60" Deck; Ser. No. 055001 & After	DMU210282		7108BR
Deck Drive; W/72" Deck; Ser. No. 055000 & Before	TCU19900		7116BR
Deck Drive; W/72" Deck; Ser. No. 055001 & After	TCU16036		6762BR
W.P.; Ser. No. 030000 & Before	M809983	9400	9400HD
W.P.; Ser. No. 030001 & After	RG60874	9400	9400HD
<b>1420</b>			
Deck Drive; W/60" Side Discharge	TCU12497		6783BR
Deck Drive; W/60" Side Discharge	TCU21054		6745BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>1420 - Continued</b>			
Deck Drive; W/62" Rear Discharge			
Deck	TCU14356		6787BR
Deck Drive; W/72" Side Discharge			
Deck; Ser. No. 060000 & Before	TCU12440		6762BR
Deck Drive; W/72" Side Discharge			
Deck; Ser. No. 060001 & After	TCU19900		7116BR
W.P.; Ser. No. 060000 & Before	M811284	7360	
W.P.; Ser. No. 060001 & After	M800347	7360	
<b>1435</b>			
Deck Drive; W/60" Side Discharge			
Deck; Ser. No. 060000 & Before	TCU12497		6783BR
Deck Drive; W/60" Side Discharge			
Deck; Ser. No. 060001 & After	TCU21054		6745BR
Deck Drive; W/62" Rear Discharge			
Deck	TCU14356		6787BR
Deck Drive; W/72" Side Discharge			
Deck; Ser. No. 060000 & Before	TCU12440		6762BR
Deck Drive; W/72" Side Discharge			
Deck; Ser. No. 060001 & After	TCU19900		7116BR
W.P.; Ser. No. 060000 & Before	M811284	7360	
W.P.; Ser. No. 060001 & After	M805011	9375	9375HD
<b>1445</b>			
Deck Drive; W/60" Side Discharge			
Deck; Ser. No. 060000 & Before	TCU12497		6783BR
Deck Drive; W/60" Side Discharge			
Deck; Ser. No. 060001 & After	TCU21054		6745BR
Deck Drive; W/62" Rear Discharge			
Deck	TCU14356		6787BR
Deck Drive; W/72" Side Discharge			
Deck; Ser. No. 060000 & Before	TCU12440		6762BR
Deck Drive; W/72" Side Discharge			
Deck; Ser. No. 060001 & After	TCU19900		7116BR
W.P.; Ser. No. 040000 & Before	M805441	9385	9385HD
W.P.; Ser. No. 040001 & After	RG60874	9400	9400HD
<b>1545</b>			
Deck Drive; W/60" Side Discharge			
Deck; Ser. No. 060000 & Before	TCU12497		6783BR
Deck Drive; W/60" Side Discharge			
Deck; Ser. No. 060001 & After	TCU21054		6745BR
Deck Drive; W/62" Rear Discharge			
Deck	TCU14356		6787BR
Deck Drive; W/72" Side Discharge			
Deck; Ser. No. 060000 & Before	TCU12440		6762BR
Deck Drive; W/72" Side Discharge			
Deck; Ser. No. 060001 & After	TCU19900		7116BR
W.P.; Ser. No. 020000 & Before	M805441	9385	9385HD
W.P.; Ser. No. 020001 & After	RG60874	9400	9400HD
<b>1550</b>			
Deck Drive; W/60" Side Discharge			
Deck	TCU32986		7093BR
Deck Drive; W/62" Rear Discharge			
Deck	TCU33435		6598BR
Deck Drive; W/72" Side Discharge			
Deck	TCU19900		7116BR
<b>1565</b>			
Deck Drive; W/60" Side Discharge			
Deck; Ser. No. 060000 & Before	TCU12497		6783BR
Deck Drive; W/60" Side Discharge			
Deck; Ser. No. 060001 & After	TCU21054		6745BR
Deck Drive; W/62" Rear Discharge			
Deck	TCU14356		6787BR
Deck Drive; W/72" Side Discharge			
Deck; Ser. No. 060000 & Before	TCU12440		6762BR
Deck Drive; W/72" Side Discharge			
Deck; Ser. No. 060001 & After	TCU19900		7116BR
W.P.; Ser. No. 030000 & Before	RG60467	9380	9380HD
<b>1570; 1575; 1580; 1585</b>			
Deck Drive; W/60" Side Discharge			
Deck	TCU32986		7093BR
Deck Drive; W/62" Rear Discharge			
Deck	TCU33435		6598BR
Deck Drive; W/72" Side Discharge			
Deck	TCU19900		7116BR
<b>1600; 1600 Series II Turbo</b>			
Fan	M801821	9390	9390HD

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>1600 Series III Turbo</b>			
Fan & Alt	UC11980	9451	9451HD
<b>1842HV</b>			
Drive; W/K61 Transaxle	M131237		6810BR
Drive; W/K62C Transaxle	M136927		7053BR
<b>1848GV</b>			
Primary	M110312		6818BR
Secondary	M110313		6650BR
<b>1848HV</b>			
Drive; W/K61 Transaxle	M131237		6810BR
Drive; W/K62C Transaxle	M136927		7053BR
Primary	M110312		6818BR
Secondary	M110313		6650BR
<b>2048HV</b>			
Drive; W/K65 Transaxle	M131237		6810BR
Drive; W/K66 Transaxle	M136927		7053BR
Primary	M110312		6818BR
Secondary	M110313		6650BR
<b>2254HV</b>			
Drive; W/K65 Transaxle	M131237		6810BR
Drive; W/K66 Transaxle	M136927		7053BR
Primary	M110312		6818BR
Secondary	M118685		6843BR
<b>2500; 2500A</b>			
Fan; W/Diesel Eng.	M800313	7345	
<b>2500B</b>			
Fan; W/Diesel Eng.; Ser. No. 020000 & Before	R81271	9380	9380HD
Fan; W/Gas Eng.	M97340		6733
<b>2500E</b>			
Fan; W/Diesel Eng.	TCU14190	K060483	
Fan; W/Gas Eng.	TCU15739	K060458	
<b>2653A</b>			
Fan	M811281	7340	
<b>2653B</b>			
Fan; Ser. No. 020119 & Before	R81271	9380	9380HD
<b>3215</b>			
Fan	M119399	9447	9447HD
W.P.	M805441	9385	9385HD
<b>3215A</b>			
Fan; W/3TNE78A/82A Eng.	M805441	9385	9385HD
Fan; W/3TNE78A-RJFE Eng.	M119399	9447	9447HD
Fan; W/3TNE84A Eng.	M805011	9375	9375HD
<b>3215B</b>			
Fan & W.P.	M805441	9385	9385HD
<b>3225B</b>			
W.P.	M805011	9375	9375HD
<b>3225C</b>			
Fan	TCU16867	9463	9463HD
W.P.	M805011	9375	9375HD
<b>3235</b>			
Fan	M119399	9447	9447HD
W.P.	M805011	9375	9375HD
<b>3235A</b>			
Fan; W/3TNE78A/82A Eng.	M805441	9385	9385HD
Fan; W/3TNE78A-RJFE Eng.	M119399	9447	9447HD
Fan; W/3TNE84A Eng.	M805011	9375	9375HD
<b>3235B</b>			
W.P.	M805011	9375	9375HD
<b>3235C; 3245C</b>			
Fan	TCU16867	9463	9463HD
W.P.	M805011	9375	9375HD
<b>7200A</b>			
Fan	TCU38089	9580	9580HD
W.P.	M82461		6839
<b>7400A</b>			
Fan	TCU38089	9580	9580HD





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>7500A</b>			
Alt .....	TCU36012	<b>K080600</b>	
Fan .....	TCU38089	<b>9580</b>	<b>9580HD</b>
<b>7700A</b>			
Fan .....	TCU38089	<b>9580</b>	<b>9580HD</b>
<b>8000A</b>			
Alt .....	TCU36012	<b>K080600</b>	
Fan .....	TCU38089	<b>9580</b>	<b>9580HD</b>
<b>8700A; 8800A; 8900A</b>			
Fan .....	TCU38089	<b>9580</b>	<b>9580HD</b>
<b>9009A</b>			
Fan .....	TCU30780	<b>9560</b>	<b>9560HD</b>
<b>D100</b>			
Deck Drive .....	GX20072		<b>6651BR</b>
Traction .....	GX22036		<b>6757BR</b>
<b>D105</b>			
Deck Drive .....	GX20072		<b>6651BR</b>
Snow Blower Attachment .....	M155452		<b>6755BR</b>
Traction .....	GX24154		<b>6944BR</b>
<b>D110; D120</b>			
Deck Drive .....	GX20072		<b>6651BR</b>
Traction .....	GX20006		<b>6690BR</b>
<b>D125</b>			
Deck Drive .....	GX20072		<b>6651BR</b>
Drive .....	GX20006		<b>6690BR</b>
<b>D130</b>			
Deck Drive .....	GX20072		<b>6651BR</b>
Traction .....	GX20006		<b>6690BR</b>
<b>D140; D150; D155; D160</b>			
Deck Drive .....	GX21833		<b>6686BR</b>
Traction .....	GX20006		<b>6690BR</b>
<b>D170</b>			
Deck Drive .....	GX21395		<b>6769BR</b>
Traction .....	GX20006		<b>6690BR</b>
<b>E100</b>			
Deck Drive .....	GX20072		<b>6651BR</b>
Snow Blower Attachment .....	M158130		<b>6717BR</b>
Traction .....	GX24154		<b>6944BR</b>
<b>E110; E120; E130</b>			
Deck Drive .....	GX20072		<b>6651BR</b>
Snow Blower Attachment .....	M158130		<b>6717BR</b>
Traction .....	GX20006		<b>6690BR</b>
<b>E140; E150; E160; E170</b>			
Deck Drive .....	GX21833		<b>6686BR</b>
Snow Blower Attachment .....	M158130		<b>6717BR</b>
Traction .....	GX20006		<b>6690BR</b>
<b>E180</b>			
Deck Drive .....	GX21395		<b>6769BR</b>
Snow Blower Attachment .....	M158130		<b>6717BR</b>
Traction .....	GX20006		<b>6690BR</b>
<b>F510; F525</b>			
Primary; W/38" Deck; Ser. No. 130000 & Before .....	M95121		<b>6843</b>
Primary; W/38" Deck; Ser. No. 130001 & After .....	M118755		<b>A42</b>
Primary; W/46" Deck .....	M95087		<b>7090BR</b>
Primary; W/48" Deck; Ser. No. 130000 & Before .....	M95121		<b>6843</b>
Primary; W/48" Deck; Ser. No. 130001 & After .....	M118755		<b>A42</b>
Secondary; W/38" Deck; Ser. No. 130000 & Before .....	M95122		<b>6798BR</b>
Secondary; W/38" Deck; Ser. No. 130001 & After .....	M120048		<b>6811BR</b>
Secondary; W/48" Deck; Ser. No. 130000 & Before .....	M95875		<b>6650BR</b>
Secondary; W/48" Deck; Ser. No. 130001 & After .....	M118756		<b>6589BR</b>

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>F620</b>			
Deck Drive; W/48" Deck .....	M131551		<b>6687BR</b>
Deck Drive; W/54" Deck .....	M136819		<b>6748BR</b>
Deck Drive; W/60" Deck .....	M135782		<b>6696BR</b>
Drive .....	M136351		<b>6406BR</b>
<b>F625</b>			
Drive .....			<b>6960</b>
<b>F680</b>			
Deck Drive; W/48" Deck .....	M131551		<b>6687BR</b>
Deck Drive; W/54" Deck .....	M136819		<b>6748BR</b>
Deck Drive; W/60" Deck .....	M135782		<b>6696BR</b>
Drive .....	M136351		<b>6406BR</b>
<b>F687</b>			
Deck Drive; W/48" Deck .....	M131551		<b>6687BR</b>
Deck Drive; W/54" Deck .....	M136819		<b>6748BR</b>
Deck Drive; W/60" Deck .....	M135782		<b>6696BR</b>
Hydro. Drive .....	M136351		<b>6406BR</b>
<b>F710</b>			
Deck .....	M111564		<b>7063BR</b>
P.T.O. ....	AM108054		<b>2 6856</b>
Traction .....	M75353		<b>6943BR</b>
<b>F725</b>			
Deck; W/54" Deck .....	M111534		<b>7096BR</b>
Deck Drive; W/48" Deck .....	M111564		<b>7063BR</b>
P.T.O. ....	AM108054		<b>6856</b>
Traction .....	M75353		<b>6943BR</b>
<b>F735</b>			
Deck; W/48" Deck .....	M111564		<b>7063BR</b>
Deck; W/54" Deck .....	M111534		<b>7096BR</b>
Deck; W/60" Deck .....	M133184		<b>6646BR</b>
P.T.O. ....	AM128033		<b>6593BR</b>
Traction .....	M139011		<b>6743BR</b>
<b>F910</b>			
Blade To Blade .....	M120381		<b>6695BR</b>
P.T.O. ....	AM100465		<b>6933</b>
<b>F911</b>			
Blade To Blade .....	M120381		<b>6695BR</b>
Fan .....	M97340		<b>6833</b>
P.T.O. ....	AM100465		<b>6933</b>
<b>F912; F915</b>			
Blade To Blade .....	M120381		<b>6695BR</b>
Fan .....	M800048	<b>7340</b>	<b>6933</b>
P.T.O. ....	AM100465		
<b>F925</b>			
Blade To Blade .....	M120381		<b>6695BR</b>
Fan .....	M800347	<b>7360</b>	<b>6933</b>
P.T.O. ....	AM100465		
<b>F930; F932; F935</b>			
Blade To Blade; W/43" Belt O.C. ....	AM102190		<b>6843</b>
Blade To Blade; W/72" Belt O.C. ....	M91365		<b>6972</b>
Deck Drive .....	M120381		<b>6695BR</b>
Fan .....	M800347	<b>7360</b>	<b>6933</b>
P.T.O. ....	AM100465		
<b>F1145</b>			
W.P. ....	M805441	<b>9385</b>	<b>9385HD</b>
<b>G100</b>			
Drive .....	M136927		<b>7053BR</b>
Primary Drive .....	M110312		<b>6818BR</b>
Secondary Drive .....	M118685		<b>6843BR</b>
<b>G110</b>			
Deck Drive .....	GX21395		<b>6769BR</b>
Drive .....	GX21407		<b>6709BR</b>
<b>GT225</b>			
Primary Drive; W/38" Deck .....	M117608		<b>6915BR</b>
Primary Drive; W/42" Deck .....	M143019		<b>6655BR</b>
Primary Drive; W/42" Mulching Deck .....	M140502		<b>7028BR</b>
Primary Drive; W/48" Deck .....	M143019		<b>6655BR</b>
Secondary Drive; W/38" Deck .....	M82462		<b>6743BR</b>
Secondary Drive; W/42" Deck .....	M43820		<b>6914BR</b>
Secondary Drive; W/42" Mulching Deck .....	M150717		<b>6773BR</b>

2 Two Required





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>GT225 - Continued</b>			
Secondary Drive; W/48" Deck	M154958		6650BR
Traction	M127523		6649BR
<b>GT235</b>			
Primary Drive; W/42" Deck	M143019		6655BR
Primary Drive; W/42" Mulching Deck	M140502		7028BR
Primary Drive; W/48" Deck	M110312		6818BR
Primary Drive; W/54" Deck	M143019		6655BR
Secondary Drive; W/42" Deck	M43820		6914BR
Secondary Drive; W/42" Mulching Deck	M150717		6773BR
Secondary Drive; W/48" Deck	M154958		6650BR
Secondary Drive; W/54" Deck	M118685		6843BR
Traction	M127523		6649BR
<b>GT242</b>			
Primary; W/38" Deck	M117608		6915BR
Primary; W/44" Deck	M77988		7097BR
Primary; W/48" Deck	M110312		6818BR
Secondary; W/38" Deck	M82462		6743BR
Secondary; W/44" Deck	M115776		6805BR
Secondary; W/48" Deck	M154958		6650BR
Traction	M114763		6775BR
<b>GT245</b>			
Primary Drive; W/38" Deck	M117608		6915BR
Primary Drive; W/42" Deck	M143019		6655BR
Primary Drive; W/42" Mulching Deck	M140502		7028BR
Primary Drive; W/48" Deck	M143019		6655BR
Primary Drive; W/54" Deck	M143019		6655BR
Secondary Drive; W/38" Deck	M82462		6743BR
Secondary Drive; W/42" Deck	M43820		6914BR
Secondary Drive; W/42" Mulching Deck	M150717		6773BR
Secondary Drive; W/48" Deck	M154958		6650BR
Secondary Drive; W/54" Deck	M154960		6574BR
Traction	M127523		6649BR
<b>GT262</b>			
Primary; W/38" Deck	M117608		6915BR
Primary; W/44" Deck	M77988		7097BR
Primary; W/48" Deck	M110312		6818BR
Secondary; W/38" Deck	M82462		6743BR
Secondary; W/44" Deck	M115776		6805BR
Secondary; W/48" Deck	M154958		6650BR
Traction	M114763		6775BR
<b>GT275</b>			
Primary; W/38" Deck	M117608		6915BR
Primary; W/44" Deck	M77988		7097BR
Primary; W/48" Deck	M110312		6818BR
Secondary; W/38" Deck	M82462		6743BR
Secondary; W/44" Deck	M115776		6805BR
Secondary; W/48" Deck	M154958		6650BR
Traction	M119713		7068BR
<b>GX70; GX75</b>			
Mower Drive	M112006		6793BR
Primary	M94020		6849
<b>GX85</b>			
Deck Drive	M112006		6793BR
Traction	M94020		A47
<b>GX95</b>			
Mower Drive	M112006		6793BR
Primary	M94020		6849
<b>GX255</b>			
Primary; W/44" Deck	M119696		6863BR
Primary; W/48" Deck	M143019		6655BR
Primary; W/54" Deck	M143019		6655BR
Secondary; W/44" Deck	M115776		6805BR
Secondary; W/48" Deck	M154958		6650BR
Secondary; W/54" Deck	M154960		6574BR
Traction	M127523		6649BR
<b>GX325; GX335; GX345; GX355</b>			
Primary; W/38" Deck	M117608		6915BR
Primary; W/42" Deck	M143019		6655BR
Primary; W/44" Deck	M119696		6863BR
Primary; W/48" Deck	M143019		6655BR
Primary; W/54" Deck	M143019		6655BR
Secondary; W/38" Deck	M82462		6743BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>GX325; GX335; GX345; GX355 - Continued</b>			
Secondary; W/42" Deck	M43820		6914BR
Secondary; W/44" Deck	M115776		6805BR
Secondary; W/48" Deck	M154958		6650BR
Secondary; W/54" Deck	M154960		6574BR
Traction	M142499		6951BR
<b>L100</b>			
Mower Drive; W/42" Deck	GX20072		6651BR
Traction	GX22036		6757BR
<b>L108</b>			
Mower Drive	GX20072		6651BR
Traction	GX20006		6690BR
<b>L110</b>			
Mower Drive; W/42" Deck	GX20072		6651BR
Traction	GX20006		6690BR
<b>L111</b>			
Drive	GX20006		6690BR
Mower Drive	GX20072		6651BR
<b>L118</b>			
Mower Drive	GX20072		6651BR
Traction	GX20006		6690BR
<b>L120</b>			
Mower Drive; Ser. No. 150000 & Before	GX20305		6652BR
Mower Drive; Ser. No. 150001 & After	GX21833		6686BR
Traction	GX20006		6690BR
<b>L130</b>			
Mower Drive; Ser. No. A130000 & Before	GX20305		6652BR
Mower Drive; Ser. No. A130001 & After	GX21833		6686BR
Mower Drive; Ser. No. B020000 & Before	GX20305		6652BR
Mower Drive; Ser. No. B020001 & After	GX21833		6686BR
Traction	GX20006		6690BR
<b>LA100</b>			
Deck Drive; W/42" Deck	GX20072		6651BR
Traction	GX22036		6757BR
<b>LA105</b>			
Eng. To Deck	GX20072		6651BR
Snow Blower Attachment	M155452		6755BR
Traction	GX22036		6757BR
<b>LA110</b>			
Deck Drive; W/42" Deck	GX20072		6651BR
Traction	GX20006		6690BR
<b>LA115</b>			
Eng. To Deck	GX20072		6651BR
Snow Blower Attachment	M155452		6755BR
Traction	GX20006		6690BR
<b>LA120</b>			
Deck Drive; W/42" Deck	GX20072		6651BR
Traction	GX20006		6690BR
<b>LA125</b>			
Eng. To Deck	GX20072		6651BR
Snow Blower Attachment	M155452		6755BR
Traction	GX20006		6690BR
<b>LA130</b>			
Deck Drive; W/48" Deck	GX21833		6686BR
Traction	GX20006		6690BR
<b>LA135LE</b>			
Deck Drive; W/42" Deck	GX20072		6651BR
Traction	GX20006		6690BR
<b>LA135SE</b>			
Eng. To Deck	GX20072		6651BR
Snow Blower Attachment	M155452		6755BR
Traction	GX20006		6690BR
<b>LA140</b>			
Deck Drive; W/48" Deck	GX21833		6686BR
Traction	GX20006		6690BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>LA145</b>			
Eng. To Deck .....	GX21833		6686BR
Snow Blower Attachment .....	M155452		6755BR
Traction .....	GX20006		6690BR
<b>LA150</b>			
Deck Drive; W/54" Deck .....	GX21395		6769BR
Traction .....	GX20006		6690BR
<b>LA165</b>			
Eng. To Deck .....	GX21833		6686BR
Snow Blower Attachment .....	M155452		6755BR
Traction .....	GX20006		6690BR
<b>LA175</b>			
Eng. To Deck .....	GX21395		6769BR
Snow Blower Attachment .....	M155452		6755BR
Traction .....	GX20006		6690BR
<b>LT133</b>			
Deck Drive; W/38" Deck .....	M126536		6684BR
Primary; W/42" Mulching Deck .....	M128733		6765BR
Secondary; W/42" Mulching Deck .....	M150717		6773BR
Traction .....	M126012		6758BR
<b>LT150</b>			
Collector .....	M47765		6412BR
Deck Drive; W/38" Deck .....	M126536		6684BR
Deck Drive; W/42" Deck .....	M126536		6684BR
Primary; W/42" Mulching Deck .....	M128733		6765BR
Secondary; W/42" Mulching Deck .....	M150717		6773BR
Snow Blower Attachment - Upper .....	M82538		6847BR
Traction; Gear Model .....	M144570		7076BR
Traction; Hydro. Model .....	M144044		6764BR
<b>LT155</b>			
Deck Drive; W/38" Deck .....	M126536		6684BR
Primary; W/42" Mulching Deck .....	M128733		6765BR
Secondary; W/42" Mulching Deck .....	M150717		6773BR
Traction .....	M126009		6503BR
<b>LT160</b>			
Collector; W/38" Deck .....	M47765		6412BR
Deck Drive; W/38", 42" Deck .....	M126536		6684BR
Primary; W/42" Mulching Deck .....	M128733		6765BR
Secondary; W/42" Mulching Deck .....	M150717		6773BR
Snow Blower Attachment - Upper .....	M82538		6847BR
Traction .....	M144044		6764BR
<b>LT166</b>			
Deck Drive; W/38" Deck .....	M126536		6684BR
Deck Drive; W/46" Deck .....	M123281		6707BR
Deck Drive; W/48" Deck .....	GX10063		6766BR
Primary; W/42" Mulching Deck .....	M128733		6765BR
Secondary; W/42" Mulching Deck; Ser. No. 095001 & After .....	M150717		6773BR
Traction .....	M126009		6503BR
<b>LT170</b>			
Deck Drive; W/38", 42" Deck .....	M126536		6684BR
Deck Drive; W/48" Deck .....	M151649		6766BR
Primary; W/42" Mulching Deck .....	M128733		6765BR
Secondary; W/42" Mulching Deck .....	M150717		6773BR
Snow Blower Attachment - Upper .....	M82538		6847BR
Traction .....	M144044		6764BR
<b>LT180</b>			
Collector; W/38" Deck .....	M47765		6412BR
Collector; W/48" Deck .....	M138974		6637BR
Deck Drive; W/38", 42" Deck .....	M126536		6684BR
Deck Drive; W/48" Deck .....	M151649		6766BR
Primary; W/42" Mulching Deck .....	M128733		6765BR
Secondary; W/42" Mulching Deck .....	M150717		6773BR
Snow Blower Attachment - Upper .....	M82538		6847BR
Traction .....	M144044		6764BR
<b>LT190</b>			
Collector .....	M138974		6637BR
Deck Drive .....	M151649		6766BR
Snow Blower Attachment - Upper .....	M82538		6847BR
Traction .....	M144044		6764BR
<b>LTR166; LTR180</b>			
Primary .....	M152630		6763BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>LTR166; LTR180 - Continued</b>			
Traction .....	M141562		7071BR
<b>LX172</b>			
Drive .....	M110367		6713BR
Primary; W/38" Deck .....	M77988		7097BR
Primary; W/44" Deck .....	M119696		6863BR
Primary; W/48" Deck .....	M110312		6818BR
Secondary; W/38" Deck .....	M82462		6743BR
Secondary; W/44" Deck .....	M115776		6805BR
Secondary; W/48" Deck .....	M110313		6650BR
<b>LX173</b>			
Drive .....	M110367		6713BR
Primary; W/38" Deck .....	M82734		6860
Primary; W/44" Deck .....	M119696		6863BR
Primary; W/48" Deck .....	M110312		6818BR
Secondary; W/38" Deck .....	M82462		6743BR
Secondary; W/44" Deck .....	M115776		6805BR
Secondary; W/48" Deck .....	M110313		6650BR
<b>LX176; LX178</b>			
Drive .....	M110978		6653BR
Primary; W/38" Deck .....	M82734		6860
Primary; W/44" Deck .....	M77988		7097BR
Primary; W/48" Deck .....	M110312		6818BR
Primary Drive; W/38" Deck .....	M77988		7097BR
Secondary; W/38" Deck .....	M82462		6743BR
Secondary; W/44" Deck .....	M115776		6805BR
Secondary; W/48" Deck .....	M154958		6650BR
<b>LX186; LX188</b>			
Drive .....	M110978		6653BR
Primary; W/38" Deck .....	M82734		6860
Primary; W/44" Deck .....	M119696		6863BR
Primary; W/48" Deck .....	M110312		6818BR
Primary Drive; W/38" Deck .....	M77988		7097BR
Secondary; W/38" Deck .....	M82462		6743BR
Secondary; W/44" Deck .....	M115776		6805BR
Secondary; W/48" Deck .....	M154958		6650BR
<b>LX266</b>			
Primary Drive; W/38" Deck .....	M117608		6915BR
Primary Drive; W/42" Deck .....	M143019		6655BR
Primary Drive; W/42" Mulching Deck .....	M140502		7028BR
Primary Drive; W/44" Deck .....	M119696		6863BR
Primary Drive; W/48" Deck .....	M143019		6655BR
Secondary Drive; W/38" Deck .....	M82462		6743BR
Secondary Drive; W/42" Deck .....	M43820		6914BR
Secondary Drive; W/42" Mulching Deck .....	M150717		6773BR
Secondary Drive; W/44" Deck .....	M115776		6805BR
Secondary Drive; W/48" Deck .....	M154958		6650BR
Traction .....	M146667		6463BR
<b>LX277</b>			
Primary Drive; W/38" Deck .....	M117608		6915BR
Primary Drive; W/42" Deck .....	M143019		6655BR
Primary Drive; W/42" Mulching Deck .....	M140502		7028BR
Primary Drive; W/44" Deck .....	M119696		6863BR
Primary Drive; W/48" Deck .....	M143019		6655BR
Secondary Drive; W/38" Deck .....	M82462		6743BR
Secondary Drive; W/42" Deck .....	M43820		6914BR
Secondary Drive; W/42" Mulching Deck .....	M150717		6773BR
Secondary Drive; W/44" Deck .....	M115776		6805BR
Secondary Drive; W/48" Deck .....	M154958		6650BR
Traction; W/2-Wheel Stg. ....	M146667		6463BR
Traction; W/4-Wheel Stg.; Ser. No. 060000 & Before .....			
Traction; W/4-Wheel Stg.; Ser. No. 060001 & After .....	M127524		6711BR
Traction; W/4-Wheel Stg.; Ser. No. 060001 & After .....	M147044		6709BR
<b>LX279</b>			
Primary Drive; W/38" Deck .....	M117608		6915BR
Primary Drive; W/42" Deck .....	M143019		6655BR
Primary Drive; W/42" Mulching Deck .....	M140502		7028BR
Primary Drive; W/44" Deck .....	M119696		6863BR
Primary Drive; W/48" Deck .....	M143019		6655BR
Secondary Drive; W/38" Deck .....	M82462		6743BR
Secondary Drive; W/42" Deck .....	M43820		6914BR
Secondary Drive; W/42" Mulching Deck .....	M150717		6773BR
Secondary Drive; W/44" Deck .....	M115776		6805BR
Secondary Drive; W/48" Deck .....	M154958		6650BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>LX279 – Continued</b>			
Traction .....	M146667		6463BR
<b>LX280</b>			
Primary Drive .....	M143019		6655BR
Secondary Drive; W/42" Deck .....	M43820		6914BR
Secondary Drive; W/48" Deck .....	M154958		6650BR
Secondary Drive; W/54" Deck .....	M154960		6574BR
Traction .....	M147044		6709BR
<b>LX288</b>			
Primary Drive .....	M143019		6655BR
Secondary Drive; W/48" Deck .....	M154958		6650BR
Secondary Drive; W/54" Deck .....	M154960		6574BR
Traction .....	M146667		6463BR
<b>LX289</b>			
Primary Drive; W/38" Deck .....	M117608		6915BR
Primary Drive; W/42" Deck .....	M143019		6655BR
Primary Drive; W/42" Mulching Deck .....	M140502		7028BR
Primary Drive; W/44" Deck .....	M119696		6863BR
Primary Drive; W/48" Deck .....	M143019		6655BR
Secondary Drive; W/38" Deck .....	M82462		6743BR
Secondary Drive; W/42" Deck .....	M43820		6914BR
Secondary Drive; W/42" Mulching Deck .....	M150717		6773BR
Secondary Drive; W/44" Deck .....	M115776		6805BR
Secondary Drive; W/48" Deck .....	M154958		6650BR
Traction .....	M147044		6709BR
<b>M653 Z-TRAK; M655 Z-TRAK</b>			
Deck Drive .....	TCU10004		6946BR
Hydro. Drive .....	TCU10002		6666BR
P.T.O. ....	TCU10003		6916BR
<b>M665 Z-TRAK</b>			
Deck Drive .....	TCU10005		6646BR
Hydro. Drive .....	TCU10002		6666BR
P.T.O. ....	TCU10003		6916BR
<b>R70; R72; R92</b>			
Deck; W/63" Belt O.C. ....	M86422		6863
Deck; W/64" Belt O.C. ....	M91330		6864
Mower .....	M82538		6847BR
Traction .....	M86421		6853
<b>RX63</b>			
Mower Drive; W/26" Deck .....	M72031		6860
Mower Drive; W/30" Deck .....	M112006		6793BR
Mower Drive; W/38" Deck .....	M112490		6899
Primary .....	M93045		6943
Secondary .....	M91470		6947
<b>RX73; RX75; RX95</b>			
Mower Drive; W/30" Deck .....	M112006		6793BR
Mower Drive; W/38" Deck .....	M112490		6899
Primary .....	M93045		6943
Secondary .....	M91470		6947
<b>S80; S82</b>			
Mower .....	M82538		6847BR
Traction .....	M82167		6851
<b>S92</b>			
Mower .....	M86248		6378
Traction .....	M82167		6851
<b>S240 Sport</b>			
Deck Drive; W/42" Deck .....	GX25232		7015BR
Deck Drive; W/48" & 54" Deck .....	UC10514		7117BR
Traction .....	GX20006		6690BR
<b>Sabre</b>			
Drive; Model No. 1842HV, 1848HV; W/K61 Transaxle .....	M131237		6810BR
Drive; Model No. 1842HV, 1848HV; W/K62C Transaxle .....	M136927		7053BR
Drive; Model No. 2048HV, 2254HV; W/K65 Transaxle .....	M131237		6810BR
Drive; Model No. 2048HV, 2254HV; W/K66 Transaxle .....	M136927		7053BR
Primary; Model No. 1848GV, 1848HV .....	M110312		6818BR
Primary; Model No. 2048HV, 2254HV .....	M110312		6818BR
Secondary; Model No. 1848GV, 1848HV .....	M110313		6650BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>Sabre – Continued</b>			
Secondary; Model No. 2048HV .....	M110313		6650BR
Secondary; Model No. 2254HV .....	M118685		6843BR
<b>SRX75; SRX95</b>			
Mower Drive; W/30" Deck .....	M112006		6793BR
Mower Drive; W/38" Deck .....	M112490		6899
Primary .....	M94049		6943
Secondary .....	M91470		6947
<b>SST15</b>			
Primary; W/42" Deck .....	M148556		6697BR
Secondary; W/42" Deck .....	M89832		6637BR
Traction; Ser. No. 050000 & Before .....	M139970		6727BR
Traction; Ser. No. 050001 & After .....	M148269		6727BR
<b>SST16</b>			
Primary; W/42" Deck .....	M148556		6697BR
Secondary; W/42" Deck .....	M89832		6637BR
Secondary; W/42" Mulching Deck .....	M143847		6685BR
Traction; Ser. No. 050000 & Before .....	M139970		6727BR
Traction; Ser. No. 050001 & After .....	M148269		6727BR
<b>SST18</b>			
Primary; Ser. No. 050001 & After .....	M148556		6697BR
Secondary .....	M154958		6650BR
Traction; Ser. No. 050000 & Before .....	M139970		6727BR
Traction; Ser. No. 050001 & After .....	M148269		6727BR
<b>STX30</b>			
Mower .....	M41960		6653BR
Traction .....	M74747		6810BR
<b>STX38</b>			
Mower; W/1-Belt Deck (Yellow Deck) .....	M125218		6758BR
Primary; W/2-Belt Deck (Black Deck) .....	M88184		6735BR
Secondary; W/2-Belt Deck (Black Deck) .....	M82462		6743BR
Traction; W/Gear Drive .....	M74747		6810BR
Traction; W/Hydro. Drive .....	M118760		6765BR
<b>STX46</b>			
Traction; W/Gear Drive .....	M74747		6810BR
Traction; W/Hydro. Drive .....	M118760		6765BR
<b>SX75</b>			
Mower Drive; W/26" Deck .....	M72031		6860
Mower Drive; W/30" Deck .....	M112006		6793BR
Mower Drive; W/38" Deck .....	M112490		6899
Primary .....	M93045		6943
Secondary .....	M91470		6947
<b>SX85</b>			
Deck .....	M112006		6793BR
Secondary .....	M94020		A47
Traction .....	M94049		6943
<b>SX95</b>			
Blade .....	M86248		6378
Deck .....	M72683		6899
Mower Drive; W/26" Deck .....	M72031		6860
Mower Drive; W/30" Deck .....	M112006		6793BR
Mower Drive; W/38" Deck .....	M112490		6899
Primary .....	M93045		6943
Secondary .....	M91470		6947
Trans. ....	M86248		6378
<b>X300</b>			
Deck; W/42" Mulching Deck; Ser. No. 150000 & Before .....	M153160		6723BR
Deck Drive; W/38" Deck; W/O Tensioner .....	M155525		6716BR
Deck Drive; W/38" Deck; W/Tensioner .....	M154601		6707BR
Deck Drive; W/42" Deck .....	M154621		7119BR
Primary; W/42" Mulching Deck; Ser. No. 150001 & After .....	M154897		6706BR
Primary Drive; W/48" Deck .....	M154897		6706BR
Secondary; W/42" Mulching Deck; Ser. No. 150001 & After .....	M138583		7095BR
Secondary Drive; W/48" Deck .....	M154958		6650BR
Snow Blower Attachment .....	M149970		6840BR
Traction; Ser. No. 040000 & Before .....	M152284		6714BR
Traction; Ser. No. 040001 & After .....	M151277		6764BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>X300R</b>			
Deck Drive .....	M155096		7077BR
Power Blower Attachment .....	M162443		6872BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M152398		7017BR
<b>X304</b>			
Deck Drive; W/42" Deck .....	M154621		7119BR
Deck Drive; W/42" Mulching Deck; Ser. No. 150000 & Before .....	M153160		6723BR
Primary; W/42" Mulching Deck; Ser. No. 150001 & After .....	M154897		6706BR
Secondary; W/42" Mulching Deck; Ser. No. 150001 & After .....	M138583		7095BR
Snow Blower Attachment .....	M149970		6840BR
Traction .....	M151277		6764BR
<b>X310</b>			
Deck Drive .....	M154621		7119BR
Snow Blower Attachment .....	M149970		6840BR
Traction .....	M144044		6764BR
<b>X320</b>			
Collector .....	M147278		6713BR
Deck Drive; W/38" Deck .....	M154601		6707BR
Deck Drive; W/42" Deck .....	M154621		7119BR
Deck Drive; W/42" Mulching Deck .....	M153160		6723BR
Deck Drive; W/48" Deck; W/Non-Rotatable Wheels .....	M155368		6722BR
Primary Drive; W/48" Deck; W/Rotatable Wheels .....	M154897		6706BR
Primary Drive; W/54" Deck .....	M154897		6706BR
Secondary Drive; W/48" Deck; W/Rotatable Wheels .....	M154958		6650BR
Secondary Drive; W/54" Deck .....	M154960		6574BR
Snow Blower Attachment .....	M149970		6840BR
Traction .....	M151277		6764BR
<b>X324</b>			
Collector .....	M147278		6713BR
Deck Drive; W/42" Deck .....	M154621		7119BR
Deck Drive; W/42" Mulching Deck .....	M153160		6723BR
Deck Drive; W/48" Deck; W/Non-Rotatable Wheels .....	M155368		6722BR
Primary Drive; W/48" Deck; W/Rotatable Wheels .....	M154897		6706BR
Secondary Drive; W/48" Deck; W/Rotatable Wheels .....	M154958		6650BR
Snow Blower Attachment .....	M149970		6840BR
Traction .....	M151277		6764BR
<b>X330</b>			
Deck Drive .....	M174994		7098BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M144044		6764BR
<b>X340</b>			
Collector .....	M146479		6627BR
Primary .....	M154897		6706BR
Secondary .....	M154960		6574BR
Snow Blower Attachment .....	M149970		6840BR
Traction .....	M151277		6764BR
<b>X350</b>			
Deck Drive; W/42" Deck .....	M174994		7098BR
Primary Drive; W/48" Deck .....	M169485		6675BR
Secondary Drive; W/48" Deck .....	M169500		6917BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M144044		6764BR
<b>X350R</b>			
Secondary Drive .....	M170986		7120BR
<b>X354</b>			
Deck Drive .....	M174994		7098BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M144044		6764BR
<b>X360</b>			
Collector .....	M147278		6713BR
Primary .....	M154897		6706BR
Secondary .....	M154958		6650BR
Snow Blower Attachment .....	M149970		6840BR
Traction .....	M151277		6764BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>X370</b>			
Deck Drive .....	M174994		7098BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M144044		6764BR
<b>X380</b>			
Primary .....	M169485		6675BR
Secondary; W/48" Deck .....	M169500		6917BR
Secondary; W/54" Deck .....	M169486		7092BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M144044		6764BR
<b>X384</b>			
Primary .....	M169485		6675BR
Secondary .....	M169500		6917BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M144044		6764BR
<b>X390</b>			
Primary .....	M169485		6675BR
Secondary; W/48" Deck .....	M169500		6917BR
Secondary; W/54" Deck .....	M169486		7092BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M144044		6764BR
<b>X394</b>			
Primary .....	M169485		6675BR
Secondary .....	M169500		6917BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M126012		6758BR
<b>X465; X475; X485; X495</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/62" Deck .....	M147279		6711BR
Secondary; W/48" Deck .....	M143888		6694BR
Secondary; W/54" Deck .....	M141627		6724BR
Secondary; W/62" Deck .....	M142997		6725BR
<b>X500</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Deck; W/48" Deck; W/Non-Rotatable Wheels .....	M155368		6722BR
Primary Drive; W/48" Deck; W/Rotatable Wheels .....	M154897		6706BR
Primary Drive; W/54" Deck .....	M154897		6706BR
Secondary; W/48" Deck; W/Rotatable Wheels .....	M154958		6650BR
Secondary Drive; W/54" Deck .....	M154960		6574BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M151276		6721BR
<b>X520</b>			
Collector .....	M146479		6627BR
Deck Drive; W/42" Deck .....	M154621		7119BR
Deck Drive; W/42" Mulching Deck .....	M153160		6723BR
Deck Drive; W/48" Deck; W/Non-Rotatable Wheels .....	M155368		6722BR
Primary Drive; W/48" Deck; W/Rotatable Wheels .....	M154897		6706BR
Primary Drive; W/54" Deck .....	M154897		6706BR
Secondary Drive; W/48" Deck; W/Rotatable Wheels .....	M154958		6650BR
Secondary Drive; W/54" Deck .....	M154960		6574BR
Snow Blower Attachment .....	M149970		6840BR
Traction .....	M151276		6721BR
<b>X530</b>			
Blower .....	M146479		6627BR
Primary Drive; W/54" Deck .....	M154897		6706BR
Secondary Drive; W/54" Deck .....	M154960		6574BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M151276		6721BR
<b>X534</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Deck; W/Non-Rotatable Wheels .....	M155368		6722BR
Primary .....	M154897		6706BR
Secondary; W/48" Deck .....	M154958		6650BR
Secondary; W/54" Deck .....	M154960		6574BR
Snow Blower Attachment .....	M149970		6840BR

Lawn & Garden Equipment





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>X534 - Continued</b>			
Traction .....	M151276		6721BR
<b>X540</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Deck; W/Non-Rotatable Wheels; W/48" Deck .....	M155368		6722BR
Primary; W/Rotatable Wheels; W/48" Deck .....	M154897		6706BR
Primary Drive; W/54" Deck .....	M154897		6706BR
Secondary; W/Rotatable Wheels; W/48" Deck .....	M154958		6650BR
Secondary Drive; W/54" Deck .....	M154960		6574BR
Snow Blower Attachment .....	M149970		6840BR
Traction .....	M151276		6721BR
<b>X570</b>			
Primary .....	M169485		6675BR
Secondary; W/48" Deck .....	M169500		6917BR
Secondary; W/54" Deck .....	M169486		7092BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M174585		6997
<b>X575</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/62" Deck .....	M147279		6711BR
Fan .....	M97340		6733
Secondary; W/48" Deck .....	M143888		6694BR
Secondary; W/54" Deck .....	M141627		6724BR
Secondary; W/62" Deck .....	M142997		6725BR
<b>X580</b>			
Primary .....	M169485		6675BR
Secondary .....	M169486		7092BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M174585		6997
<b>X584</b>			
Primary .....	M169485		6675BR
Secondary; W/48" Deck .....	M169500		6917BR
Secondary; W/54" Deck .....	M169486		7092BR
Snow Blower Attachment .....	M174506		6840BR
Traction .....	M174585		6997
<b>X585</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/62" Deck .....	M147279		6711BR
Secondary; W/48" Deck .....	M143888		6694BR
Secondary; W/54" Deck .....	M141627		6724BR
Secondary; W/62" Deck .....	M142997		6725BR
<b>X590</b>			
Primary; Ser. No. 110000 & Before; W/54" Deck .....	M172924		6855BR
Primary; Ser. No. 110001 & After; W/54" Deck .....	M169485		6675BR
Primary; W/48" Deck .....	M169485		6675BR
Secondary; Ser. No. 110000 & Before; W/54" Deck .....	M154960		6574BR
Secondary; Ser. No. 110001 & After; W/54" Deck .....	M169486		7092BR
Secondary; W/48" Deck .....	M169500		6917BR
Snow Blower Attachment .....	M174506		6840BR
<b>X595</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/62" Deck .....	M147279		6711BR
Secondary; W/48" Deck .....	M143888		6694BR
Secondary; W/54" Deck .....	M141627		6724BR
Secondary; W/62" Deck .....	M142997		6725BR
<b>X700</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/60" 7-Iron Deck .....	TCU16122		7014BR
Collector; W/62" Deck .....	M147279		6711BR
Fan .....	M97340		6733
Secondary; W/48" Deck .....	M143888		6694BR
Secondary; W/54" Deck .....	M141627		6724BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>X700 - Continued</b>			
Secondary; W/60" 7-Iron Deck .....	M120381		6695BR
Secondary; W/62" Deck .....	M142997		6725BR
<b>X710</b>			
Alt .....	M153381		6741
Deck Drive; W/48" Deck .....	M163989		7078BR
Deck Drive; W/54" Deck .....	M165156		7078BR
Deck Drive; W/60" Deck .....	M163993		7079BR
Fan .....	M97340		6733
<b>X720; X720SE</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/60" 7-Iron Deck .....	TCU16122		7014BR
Collector; W/62" Deck .....	M147279		6711BR
Fan .....	M147344	7335	
Secondary; W/48" Deck .....	M143888		6694BR
Secondary; W/54" Deck .....	M141627		6724BR
Secondary; W/60" 7-Iron Deck .....	M120381		6695BR
Secondary; W/62" Deck .....	M142997		6725BR
<b>X724</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/62" Deck .....	M147279		6711BR
Fan .....	M147344	7335	
Secondary; W/48" Deck .....	M143888		6694BR
Secondary; W/54" Deck .....	M141627		6724BR
Secondary; W/62" Deck .....	M142997		6725BR
<b>X728</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/60" 7-Iron Deck .....	TCU16122		7014BR
Collector; W/62" Deck .....	M147279		6711BR
Fan .....	M147344	7335	
Secondary; W/48" Deck .....	M143888		6694BR
Secondary; W/54" Deck .....	M141627		6724BR
Secondary; W/60" 7-Iron Deck .....	M120381		6695BR
Secondary; W/62" Deck .....	M142997		6725BR
<b>X728SE</b>			
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/60" 7-Iron Deck .....	TCU16122		7014BR
Collector; W/62" Deck .....	M147279		6711BR
Fan .....	M147344	7335	
Secondary; W/54" Deck .....	M141627		6724BR
Secondary; W/60" 7-Iron Deck .....	M120381		6695BR
Secondary; W/62" Deck .....	M142997		6725BR
<b>X729</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/62" Deck .....	M147279		6711BR
Fan .....	M147344	7335	
Secondary; W/48" Deck .....	M143888		6694BR
Secondary; W/54" Deck .....	M141627		6724BR
Secondary; W/62" Deck .....	M142997		6725BR
<b>X730; X734; X738; X739</b>			
Alt .....	M153381		6741
Deck Drive; W/48" Deck .....	M163989		7078BR
Deck Drive; W/54" Deck .....	M165156		7078BR
Deck Drive; W/60" Deck .....	M163993		7079BR
Fan .....	M97340		6733
<b>X740</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/60" 7-Iron Deck .....	TCU16122		7014BR
Collector; W/62" Deck .....	M147279		6711BR
Fan; Ser. No. 030000 & Before .....	RG60467	9380	9380HD
Fan; Ser. No. 030001 & After .....	M805441	9385	9385HD
Secondary; W/48" Deck .....	M143888		6694BR
Secondary; W/54" Deck .....	M141627		6724BR
Secondary; W/60" 7-Iron Deck .....	M120381		6695BR
Secondary; W/62" Deck .....	M142997		6725BR
<b>X744</b>			
Collector; W/48" Deck .....	M147278		6713BR
Collector; W/54" Deck .....	M146479		6627BR
Collector; W/62" Deck .....	M147279		6711BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>X744 – Continued</b>			
Fan; Ser. No. 030000 & Before	RG60467	9380	9380HD
Fan; Ser. No. 030001 & After	M805441	9385	9385HD
Secondary; W/48" Deck	M143888		6694BR
Secondary; W/54" Deck	M141627		6724BR
Secondary; W/62" Deck	M142997		6725BR
<b>X748; X748SE</b>			
Collector; W/48" Deck	M147278		6713BR
Collector; W/54" Deck	M146479		6627BR
Collector; W/60" 7-Iron Deck	TCU16122		7014BR
Collector; W/62" Deck	M147279		6711BR
Fan; Ser. No. 030000 & Before	RG60467	9380	9380HD
Fan; Ser. No. 030001 & After	M805441	9385	9385HD
Secondary; W/48" Deck	M143888		6694BR
Secondary; W/54" Deck	M141627		6724BR
Secondary; W/60" 7-Iron Deck	M120381		6695BR
Secondary; W/62" Deck	M142997		6725BR
<b>X749</b>			
Collector; W/48" Deck	M147278		6713BR
Collector; W/54" Deck	M146479		6627BR
Collector; W/62" Deck	M147279		6711BR
Fan	M805441	9385	9385HD
Secondary; W/48" Deck	M143888		6694BR
Secondary; W/54" Deck	M141627		6724BR
Secondary; W/62" Deck	M142997		6725BR
<b>X750; X754; X758</b>			
Alt	M153381		6741
Collector; W/48" Deck	M147278		6713BR
Collector; W/54" Deck	M146479		6627BR
Collector; W/60" Deck	TCU16122		7014BR
Deck Drive; W/48" Deck	M163989		7078BR
Deck Drive; W/54" Deck	M165156		7078BR
Deck Drive; W/60" Deck	M163993		7079BR
Fan	MIU800108	9370	9370HD
<b>Z225</b>			
Deck	M154294		6874BR
Transaxle; Ser. No. 100000 & Before	M155343		6712BR
Transaxle; Ser. No. 100001 & After	M160571		6781BR
<b>Z235</b>			
Deck Drive	M154294		6874BR
Traction	M165413		6863
<b>Z245</b>			
Deck Drive; Ser. No. 10000 & Before	M154621		7119BR
Deck Drive; Ser. No. 100001 & After	M158130		6717BR
Transaxle; Ser. No. 100000 & Before	M155343		6712BR
Transaxle; Ser. No. 100001 & After	M160571		6781BR
<b>Z255</b>			
Deck Drive	GX21833		6686BR
Traction	M165413		6863
<b>Z335E</b>			
Deck Drive	GX25628		6715BR
Traction	M165413		6863
<b>Z335M; Z345M; Z345R</b>			
Deck Drive	GX25628		6715BR
Traction	GX26401		6530BR
<b>Z355E</b>			
Deck Drive	GX21833		6686BR
Traction	M165413		6863
<b>Z355R; Z375R</b>			
Deck Drive	GX26422		7118BR
Traction	GX26401		6530BR
<b>Z425</b>			
Blower; W/48" Deck	M147278		6713BR
Blower; W/54" Deck	M146479		6627BR
Deck; W/54" Deck	M158131		6718BR
Deck Drive; W/48" Deck; Ser. No. 100000 & Before	M158130		6717BR
Deck Drive; W/48" Deck; Ser. No. 100001 & After	M158131		6718BR
Hydro. Drive; Ser. No. 100000 & Before	M154157		A40
Hydro. Drive; Ser. No. 100001 Thru 130000	M160571		6781BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>Z425 – Continued</b>			
Hydro. Drive; Ser. No. 130001 & After	M169705		7029BR
<b>Z435</b>			
Deck Drive	M158131		6718BR
Hydro. Drive	M169705		7029BR
<b>Z445</b>			
Blower; W/48" Deck	M147278		6713BR
Blower; W/54" Deck	M146479		6627BR
Deck; W/54" Deck	M158131		6718BR
Deck; W/54" High Capacity Deck	M158409		6997BR
Deck Drive; W/48" Deck; Ser. No. 100000 & Before	M158130		6717BR
Deck Drive; W/48" Deck; Ser. No. 100001 & After	M158131		6718BR
Hydro. Drive; Ser. No. 100000 & Before	M154157		A40
Hydro. Drive; Ser. No. 100001 Thru 130000	M160571		6781BR
Hydro. Drive; Ser. No. 130001 & After	M169705		7029BR
<b>Z465</b>			
Deck Drive	M156261		6853BR
Hydro. Drive; Ser. No. 100000 & Before	M154157		A40
Hydro. Drive; Ser. No. 100001 Thru 130000	M160571		6781BR
Hydro. Drive; Ser. No. 130001 & After	M169705		7029BR
<b>Z525E; Z535M; Z535R</b>			
Deck Drive	GX25998		7070BR
Traction	M172116		7080BR
<b>Z540M</b>			
Deck Drive; W/48" & 54" Deck	GX25998		7070BR
Deck Drive; W/62" Deck	M172963		6878BR
Traction	M172116		7080BR
<b>Z540R</b>			
Deck Drive; W/48" & 54" Deck	GX25998		7070BR
Deck Drive; W/60" Deck	M172963		6878BR
Traction	M172116		7080BR
<b>Z625</b>			
Deck Drive	TCU19609		7093BR
Hydro. Drive	M169705		7029BR
<b>Z645</b>			
Deck Drive	M160912		6786BR
Hydro. Drive; Ser. No. 130000 & Before	M160956		6620BR
Hydro. Drive; Ser. No. 130001 & After	M163540		6763BR
<b>Z655</b>			
Deck Drive	TCU19609		7093BR
Hydro. Drive; Ser. No. 130000 & Before	M160956		6620BR
Hydro. Drive; Ser. No. 130001 & After	M163540		6763BR
<b>Z665</b>			
Deck Drive	M156261		6853BR
Hydro. Drive; Ser. No. 130000 & Before	M160956		6620BR
Hydro. Drive; Ser. No. 130001 & After	M163540		6763BR
<b>Z710A</b>			
Deck Drive; W/48" Deck; Ser. No. 020000 & Before	TCU26290		6598BR
Deck Drive; W/48" Deck; Ser. No. 020001 & After	TCU29452		7082BR
Deck Drive; W/54" Deck; Ser. No. 020000 & Before	TCU26291		6569BR
Deck Drive; W/54" Deck; Ser. No. 020001 & After	TCU29453		6868BR
Traction; Ser. No. 020000 & Before	TCU26349		7013BR
Traction; Ser. No. 020001 & After	TCU28434		7056BR
<b>Z720A</b>			
Deck Drive; W/60" Deck; Ser. No. 020000 & Before	TCU26293		6919BR
Deck Drive; W/60" Deck; Ser. No. 020001 & After	TCU29454		6869BR
Traction; Ser. No. 020000 & Before	TCU26349		7013BR
Traction; Ser. No. 020001 & After	TCU28434		7056BR
<b>Z810A Z-TRAK</b>			
Deck Drive; W/48" Deck	TCU26907		6859BR
Deck Drive; W/54" Deck	TCU26908		6770BR
Traction	TCU22550		6862BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>Z820A Z-TRAK</b>			
Deck Drive; W/48" Deck .....	TCU26907		6859BR
Deck Drive; W/54" Deck .....	TCU26908		6770BR
Deck Drive; W/60" Deck .....	TCU26909		6860BR
Traction .....	TCU22550		6862BR
<b>Z830A Z-TRAK</b>			
Deck Drive; W/54" Deck .....	TCU26908		6770BR
Deck Drive; W/60" Deck .....	TCU26909		6860BR
Deck Drive; W/72" Deck .....	TCU26910		6870BR
Traction .....	TCU22550		6862BR
<b>Z840A Z-TRAK</b>			
Deck Drive; W/54" Deck .....	TCU26908		6770BR
Deck Drive; W/60" Deck .....	TCU26909		6860BR
Traction .....	TCU22550		6862BR
<b>Z850A Z-TRAK; Z860A Z-TRAK</b>			
Deck Drive; W/60" Deck .....	TCU26909		6860BR
Deck Drive; W/72" Deck .....	TCU26910		6870BR
Traction .....	TCU22550		6862BR
<b>Z910A</b>			
Deck Drive; W/48" Deck; Ser. No. 020000 & Before .....	TCU26294		6997BR
Deck Drive; W/48" Deck; Ser. No. 020001 & After .....	TCU29452		7082BR
Deck Drive; W/54" Deck; Ser. No. 020000 & Before .....	TCU26295		7049BR
Deck Drive; W/54" Deck; Ser. No. 020001 & After .....	TCU29453		6868BR
Traction; Ser. No. 020000 & Before .....	TCU26349		7013BR
Traction; Ser. No. 020001 & After .....	TCU28434		7056BR
<b>Z915B; Z915E</b>			
Deck Drive; W/48" Deck .....	TCU30510		7083BR
Deck Drive; W/54" Deck .....	TCU31132		7001BR
Deck Drive; W/60" Deck .....	TCU35604		7086BR
Traction .....	TCU34299		7030BR
<b>Z920A</b>			
Deck Drive; W/48" Deck; Ser. No. 020000 & Before .....	TCU26294		6997BR
Deck Drive; W/48" Deck; Ser. No. 020001 & After .....	TCU29452		7082BR
Deck Drive; W/54" Deck; Ser. No. 020000 & Before .....	TCU26295		7049BR
Deck Drive; W/54" Deck; Ser. No. 020001 & After .....	TCU29453		6868BR
Deck Drive; W/60" Deck; Ser. No. 020000 & Before .....	TCU26297		6844BR
Deck Drive; W/60" Deck; Ser. No. 020001 & After .....	TCU29454		6869BR
Traction; Ser. No. 020000 & Before .....	TCU26349		7013BR
Traction; Ser. No. 020001 & After .....	TCU28434		7056BR
<b>Z920M</b>			
Deck Drive; W/48" Deck .....	TCU30510		7083BR
Deck Drive; W/54" Deck .....	TCU31132		7001BR
Deck Drive; W/60" Deck .....	TCU35604		7086BR
Traction .....	TCU34299		7030BR
<b>Z920R</b>			
Deck Drive; W/48" Deck .....	TCU30510		7083BR
Deck Drive; W/54" Deck .....	TCU31132		7001BR
Traction .....	TCU34299		7030BR
<b>Z925A</b>			
Deck Drive; W/54" Deck; Ser. No. 020000 & Before .....	TCU26295		7049BR
Deck Drive; W/54" Deck; Ser. No. 020001 & After .....	TCU29453		6868BR
Deck Drive; W/60" Deck; Ser. No. 020000 & Before .....	TCU26297		6844BR
Deck Drive; W/60" Deck; Ser. No. 020001 & After .....	TCU29454		6869BR
Traction; Ser. No. 020000 & Before .....	TCU25673		6861BR
Traction; Ser. No. 020001 & After .....	TCU28433		6846BR
<b>Z925A EFI</b>			
Deck Drive; W/54" Deck .....	TCU29453		6868BR
Deck Drive; W/60" Deck .....	TCU29454		6869BR
Traction .....	TCU28433		6846BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>Z925M</b>			
Deck Drive; W/54" Deck .....	TCU31132		7001BR
Deck Drive; W/60" Deck .....	TCU35604		7086BR
Traction .....	TCU34299		7030BR
<b>Z930A</b>			
Deck Drive; W/60" Deck; Ser. No. 020000 & Before .....	TCU26297		6844BR
Deck Drive; W/60" Deck; Ser. No. 020001 & After .....	TCU29454		6869BR
Deck Drive; W/72" Deck; Ser. No. 020000 & Before .....	TCU26298		7085BR
Deck Drive; W/72" Deck; Ser. No. 020001 & After .....	TCU29455		7084BR
Traction; Ser. No. 020000 & Before .....	TCU25673		6861BR
Traction; Ser. No. 020001 & After .....	TCU28433		6846BR
<b>Z930M</b>			
Deck Drive; W/60" Deck .....	TCU35604		7086BR
Deck Drive; W/72" Deck .....	TCU31194		7002BR
Traction .....	TCU34299		7030BR
<b>Z930R</b>			
Deck Drive; W/54" Deck .....	TCU31132		7001BR
Deck Drive; W/60" Deck .....	TCU35604		7086BR
Traction .....	TCU34299		7030BR
<b>Z945M EFI</b>			
Deck Drive; W/60" Deck .....	TCU35604		7086BR
Traction .....	TCU34299		7030BR
<b>Z950A</b>			
Deck Drive; W/60" Deck; Ser. No. 020000 & Before .....	TCU26297		6844BR
Deck Drive; W/60" Deck; Ser. No. 020001 & After .....	TCU29454		6869BR
Deck Drive; W/72" Deck; Ser. No. 020000 & Before .....	TCU26298		7085BR
Deck Drive; W/72" Deck; Ser. No. 020001 & After .....	TCU29455		7084BR
Traction; Ser. No. 020000 & Before .....	TCU25673		6861BR
Traction; Ser. No. 020001 & After .....	TCU28433		6846BR
<b>Z950M; Z950R; Z955M</b>			
Deck Drive; W/60" Deck .....	TCU35604		7086BR
Deck Drive; W/72" Deck .....	TCU31194		7002BR
Traction .....	TCU34299		7030BR
<b>Z960A</b>			
Deck Drive; W/60" Deck; Ser. No. 020000 & Before .....	TCU26297		6844BR
Deck Drive; W/60" Deck; Ser. No. 020001 & After .....	TCU29454		6869BR
Deck Drive; W/72" Deck; Ser. No. 020000 & Before .....	TCU26298		7085BR
Deck Drive; W/72" Deck; Ser. No. 020001 & After .....	TCU29455		7084BR
Traction; Ser. No. 020000 & Before .....	TCU25673		6861BR
Traction; Ser. No. 020001 & After .....	TCU28433		6846BR
<b>Z960M; Z960R</b>			
Deck Drive; W/60" Deck .....	TCU35604		7086BR
Deck Drive; W/72" Deck .....	TCU31194		7002BR
Traction .....	TCU34299		7030BR
<b>Z970A</b>			
Deck Drive; W/72" Deck; Ser. No. 020000 & Before .....	TCU26298		7085BR
Deck Drive; W/72" Deck; Ser. No. 020001 & After .....	TCU29455		7084BR
Traction; Ser. No. 020000 & Before .....	TCU25673		6861BR
Traction; Ser. No. 020001 & After .....	TCU28433		6846BR
<b>Z970R</b>			
Deck Drive; W/72" Deck .....	TCU31194		7002BR
Traction .....	TCU34299		7030BR
<b>Z997R</b>			
Deck Drive; W/60" Deck; W/Rear Discharge .....	DMU210479		7109BR
Deck Drive; W/60" Side Discharge .....	DMU210282		7108BR
Deck Drive; W/72" Deck .....	TCU19900		7116BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>K-MART</b>			
<b>135-504</b>			
Eng. To Variator .....	7540241		6494BR
Variator To Trans. ....	7540240		6511BR
<b>145-834</b>			
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540244		6840
<b>KUBOTA</b>			
<b>F2000</b>			
Fan & Alt. ....	FM355	7355	
<b>F2100</b>			
Fan & Alt. ....		7365	
<b>F2400; F2560</b>			
Fan & Alt. ....	FM376	7385	
<b>F2680E</b>			
Blade Drive; W/60" Deck .....	K5647-34710		6795BR
Blade Drive; W/72" Deck .....	K5677-34710		7104BR
<b>F3060</b>			
Fan .....	14911-97010		6738
<b>F3080; F3680</b>			
Blade Drive; W/60" Deck .....	K5647-34710		6795BR
Blade Drive; W/72" Deck .....	K5677-34710		7104BR
<b>G1800; G1900; G2000; G2100</b>			
Fan .....	15881-97010	7345	
P.T.O. ....	66101-25080		ⓂBX31
<b>G2160</b>			
Blade Drive; W/54" Deck .....	K5351-34710		6796BR
Blade Drive; W/60" Deck .....	K5763-34710		7103BR
Fan .....	15881-97010	7345	
<b>G2160-R485</b>			
Fan .....	15881-97010	7345	
<b>G2460G</b>			
Blade Drive; W/54" Deck .....	K5351-34710		6796BR
Blade Drive; W/60" Deck .....	K5763-34710		7103BR
Fan .....	15881-97010	7345	
<b>GF1800</b>			
Fan .....	15881-97010	7345	
<b>GR2000</b>			
Deck Drive .....	K5201-71410		6858BR
Fan .....	15881-97010	7345	
<b>GR2010; GR2020</b>			
Deck Drive; W/48" Deck .....	K5201-71410		6858BR
Fan .....	15881-97010	7345	
<b>GR2100</b>			
Deck Drive; W/54" Deck .....	K5221-71410		6980BR
Fan .....	15881-97010	7345	
<b>GR2110</b>			
Deck Drive; W/48" Deck .....	K5201-71410		6858BR
Deck Drive; W/54" Deck .....	K5221-71410		6980BR
Fan .....	15881-97010	7345	
<b>GR2120</b>			
Deck Drive; W/54" Deck .....	K5221-71410		6980BR
Fan .....	15881-97010	7345	
<b>T1400</b>			
Eng. To Deck .....	707134770		6979
<b>T1880; T2080</b>			
Eng. To Deck; W/42" Deck .....	K5123-71420		6482BR
<b>T2380</b>			
Eng. To Deck; W/48" Deck .....	K5123-71420		6482BR
<b>TG1860G</b>			
Blade Drive; W/48" Deck .....	K5201-71410		6858BR
Blade Drive; W/54" Deck .....	K5221-71410		6980BR
<b>ZD21</b>			
Blade Drive; W/60" Deck .....	K5647-34710		6795BR
Fan .....	15881-97010	7345	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>KUBOTA - Continued</b>			
<b>ZD221</b>			
Blade Drive; W/48" Deck .....	K5700-34712		7102BR
Blade Drive; W/54" Deck .....	K5764-34711		6797BR
Fan .....	15881-97010	7345	
<b>ZD321</b>			
Blade Drive; W/54" Deck .....	K5351-34710		6796BR
Blade Drive; W/60" Deck .....	K5647-34710		6795BR
Fan .....	15881-97010	7345	
<b>ZD323</b>			
Blade Drive; W/60" Deck .....	K5647-34710		6795BR
Fan .....	15881-97010	7345	
<b>ZD326; ZD331</b>			
Blade Drive; W/60" Deck .....	K5647-34710		6795BR
Blade Drive; W/72" Deck .....	K5677-34710		7104BR
<b>ZG20</b>			
Blade Drive; W/48" Deck .....	K5201-71410		6858BR
<b>ZG23</b>			
Blade Drive; W/54" Deck .....	K5221-71410		6980BR
<b>ZG222</b>			
Blade Drive; W/48" Deck .....	K5700-34712		7102BR
<b>ZG227</b>			
Blade Drive; W/54" Deck .....	K5764-34710		6797BR
Blade Drive; W/60" Deck .....	K5647-34710		6795BR
<b>ZG327P</b>			
Blade Drive; W/60" Deck .....	K5647-34710		6795BR
<b>ZG332P</b>			
Deck Drive; W/60" Deck .....	K5647-34710		6795BR
Deck Drive; W/72" Deck .....	K5677-34710		7104BR
Fan .....	16883-97010	7350	
<b>LAMBERT</b>			
<b>45A; 60A; 450; 450E</b>			
Blade .....	45309		6833
<b>655</b>			
Blade .....	45309		6833
Trans. ....	45303		6838
<b>955</b>			
Blade .....	95324B		6843
Drive .....	95233		6949
<b>LAND PRIDE</b>			
<b>AFM 40133</b>			
Blade .....	816-142C		6856BR
<b>AFR 4050</b>			
Blade .....			6981
P.T.O. ....			6973
Reel Drive .....			6967
<b>AVF 4050 5GANG</b>			
Blade .....			6981
P.T.O. Drive .....			6973
Vari-Cut Drive .....			6971
<b>Z44</b>			
Deck Drive .....	816-465C		6785BR
<b>Z48</b>			
Deck Drive .....	816-465C		6785BR
Hydro. Drive .....	816-616C		6861BR
<b>Z52</b>			
Deck Drive .....	816-533C		6599BR
<b>Z54</b>			
Deck Drive .....	816-639C		6567BR
Hydro. Drive .....	816-616C		6861BR
<b>ZSR54</b>			
Deck Drive; Ser. No. 774661 & Before ...	816-639C		6567BR
Deck Drive; Ser. No. 774662 & After .....	816-784C		6567BR
Hydro. Drive; Ser. No. 848900 & Before ..	816-616C		6861BR
Hydro. Drive; Ser. No. 848901 & After ....	816-779C		7013BR

ⓂTwo Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>LAND PRIDE - Continued</b>			
<b>ZSR60</b>			
Deck Drive; Ser. No. 774683 & Before ...	816-614C		6597BR
Deck Drive; Ser. No. 774684 & After .....	816-783C		6598BR
Hydro. Drive; Ser. No. 848900 & Before ..	816-616C		6861BR
Hydro. Drive; Ser. No. 848901 & After ....	816-779C		7013BR
<b>ZST40</b>			
Deck Drive .....	816-675C		6918BR
Trans. ....	816-779C		7013BR
<b>ZST48</b>			
Deck Drive .....	816-676C		6759BR
Trans. ....	816-779C		7013BR
<b>ZT60</b>			
Hydro. Drive .....	816-583C		6890BR
<b>ZT60i</b>			
Hydro. Drive .....	816-616C		6861BR
<b>ZT72</b>			
Deck Drive .....	816-525C		6934BR
Hydro. Drive .....	816-583C		6890BR
<b>ZT72i</b>			
Hydro. Drive .....	816-616C		6861BR
<b>ZT360</b>			
Deck Drive .....	816-782C		6879BR
Hydro. Drive .....	816-780C		6482BR
<b>ZT372</b>			
Hydro. Drive .....	816-780C		6482BR
<b>ZXT54</b>			
Deck Drive .....	816-594C		6853BR
Hydro. Drive .....	816-589C		6530BR
<b>ZXT60</b>			
Deck Drive .....	816-596C		6893BR
Hydro. Drive .....	816-589C		6530BR
<b>LASTEC</b>			
<b>325E</b>			
Deck .....			6989
<b>X Series</b>			
Deck .....			6963
Drive .....			6961
<b>LAWN BOY</b>			
<b>9266</b>			
Drive .....	608014T		6835
Mower Drive .....	608016	2540	6854
<b>9269</b>			
Drive .....	608016	2540	6854
<b>9300</b>			
Blade .....	605711		6861
<b>9301; 9302; 9302E; 9303; 9303E</b>			
Primary .....	606248		6833
Secondary .....	606250		6852
<b>9328; 9328E; 9328ES</b>			
Blade .....	608015T		6853
Drive .....	608014T		6835
Mower .....	607980		6862
<b>9329; 9329E; 9329ES</b>			
Blade; 1976-1974 .....	608476		6856
Drive .....	608014T		6835
Mower; 1976-1974 .....	608474		6862
<b>9368; 9368E; 9368ES</b>			
Blade .....	608025T		6868
Mower Drive .....	608017		6865
<b>9369; 9369E; 9369ES</b>			
Blade; 1976-1974 .....	608475		6870
Drive .....	608014T		6835
<b>9500; 9501</b>			
Drive .....	607271		6844
Intermediate To Blade .....	606508		6848

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>LAWN BOY - Continued</b>			
<b>9500; 9501 - Continued</b>			
Primary .....	607270		6832
<b>9600; 9601</b>			
Intermediate To Blade .....	606508		6848
<b>LT11; LT12; LT12H</b>			
Eng. To Deck .....	245477		6884
<b>M70BC</b>			
Belt; W/37" Belt O.C. ....	103324	2370	6837
Belt; W/78" Belt O.C. ....	103351		6978
Trans. ....	103347	3510	6951
<b>YT16</b>			
Eng. To Deck .....	GB235000		6950
<b>LAWN CHIEF</b>			
<b>1-836; 2-1136</b>			
Blade .....	21649		6449BR
Cross Drive .....			6844
Trans. ....	21615		6895
<b>4-525</b>			
Blade .....	20717		6856
Trans. ....	20716		6837
<b>5-830</b>			
Blade .....	21649		6449BR
Trans. ....	20716		6837
<b>LC5-8TB</b>			
Drive .....	136705		6834
<b>LC11TB</b>			
Trans. ....	171215		6882
<b>LC12TB</b>			
Trans. ....			6885
<b>LC14TB</b>			
Trans. ....	135194		6889
<b>LC18TB</b>			
Trans. ....			6888
<b>LC26BB</b>			
Blade .....	136887		6843
<b>LC32BB</b>			
Drive .....	136762		6868
<b>LC36BB</b>			
Blade .....			6975
<b>LC39/45BB</b>			
Blade .....	136176		6978
<b>LC45BB09</b>			
Blade .....	135863	2405	
<b>LAWN KEEPER</b>			
<b>8 H.P.</b>			
Eng. To Deck; W/30" Deck .....			6839
<b>11 H.P.</b>			
Eng. To Deck; W/36" Deck .....	62828		6870
<b>12 H.P.</b>			
Deck; W/36" Deck .....	62828		6870
Eng. To Transaxle; W/36" Deck .....	121979X		6463BR
<b>LAWN ROVR</b>			
<b>876; 877; 1076; 1177; 1178</b>			
Eng. To Trans. ....			6872
Mower; W/35" Belt O.C. ....			6835
Mower; W/44" Belt O.C. ....			6844
Mower; W/56" Belt O.C. ....		2560	6856
Mower; W/77" Belt O.C. ....			6877
<b>LXINGTON</b>			
<b>FCR-32 Model 190400</b>			
Blade; W/46" Belt O.C. ....		3460	6946
Blade; W/54" Belt O.C. ....		3540	6954
Drive; W/36" Belt O.C. ....		3360	6936



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>LEXINGTON - Continued</b>			
<b>FCR-32 Model 190400 - Continued</b>			
Drive; W/58" Belt O.C. ....		3580	6958
<b>MASSEY FERGUSON</b>			
<b>24 Deluxe; 24 Std.; 24S Deluxe; 24S Std.</b>			
Blade .....	1023564M1	2250	6825
Gear Box .....	1023608M1		6829
<b>2409G</b>			
Drive; Mfr. No. 1692489 .....	1676460		6843
<b>2411G</b>			
Drive; Mfr. No. 1692823, 1693048, 1693319 .....	1676460		6843
<b>2512G</b>			
Drive; Mfr. No. 1692493 .....	1708114		6895
<b>2512H</b>			
Drive; Mfr. No. 1692495 .....	170164		6877
<b>2514G</b>			
Drive; Mfr. No. 1692597, 1693100, 1693345 .....	1657044		6521BR
<b>2514H</b>			
Drive; Mfr. No. 1692591 .....	1672135		6523BR
Drive; Mfr. No. 1693102, 1693347 .....	1717397		6798BR
<b>2515H</b>			
Drive; Mfr. No. 1693546 .....	1717397		6798BR
<b>2516H</b>			
Drive; Mfr. No. 1692835 .....	1719819		6434BR
Drive; Mfr. No. 1693104, 1693349, 1693548 .....	1717397		6798BR
<b>2517H</b>			
Drive; Mfr. No. 1693550 .....	1717397		6798BR
<b>2518H; 2520H</b>			
Deck Drive; W/38" Deck; W/Narrow Pulley .....	1723025		6714BR
Drive .....	1728008		6709BR
<b>2522H</b>			
Deck Drive; W/44" Deck; W/Large Pulley .....	1729627		6848BR
Drive .....	1728008		6709BR
<b>2524H</b>			
Deck Drive; W/50" Deck; W/Narrow Pulley .....	1703466		6484BR
Drive .....	1728008		6709BR
<b>2614H</b>			
Drive; Mfr. No. 1692497 .....	1672135		6523BR
<b>2615H</b>			
Drive; Mfr. No. 1692815 .....	1672135		6523BR
Drive; Mfr. No. 1693064, 1693372, 1693598 .....	1717932		6811BR
<b>2616H</b>			
Drive; Mfr. No. 1692817 .....	1672135		6523BR
Drive; Mfr. No. 1693066, 1693374, 1693622 .....	1717932		6811BR
Drive; Mfr. No. 1693700 .....	1719819		6434BR
Drive; Mfr. No. 1693845 .....	1719819		6434BR
<b>2616HV</b>			
Drive; Mfr. No. 1692499 .....	1672135		6523BR
<b>2618H</b>			
Drive; Mfr. No. 1693279, 1693604 .....	1717932		6811BR
<b>2620H</b>			
Drive .....	1726841		6710BR
Primary; W/44" Deck .....	1601672		6799BR
Secondary; W/44" Deck .....	1721532		6798BR
<b>2717H</b>			
Drive; Mfr. No. 1692854 .....	1707381		6503BR
Drive; Mfr. No. 1693401 .....	1719398		6714BR
<b>2718H</b>			
Drive; Mfr. No. 1692501 .....	170164		6877

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MASSEY FERGUSON - Continued</b>			
<b>2718H - Continued</b>			
Drive; Mfr. No. 1692580, 1692843 .....	1707381		6503BR
Drive; Mfr. No. 1693403 .....	1719398		6714BR
<b>2720H</b>			
Drive; W/P.S.; Mfr. No. 1693405 .....	1719398		6714BR
<b>2723H</b>			
Drive .....	1721392		6710BR
Primary; W/50" Deck .....	1707740		6869
Secondary; W/50" Deck .....	1703836		6524BR
<b>2818H</b>			
Drive; Mfr. No. 1692503, 1692849, 1692955, 1693417 .....	1650502		6422BR
Drive; W/P.S.; Mfr. No. 1692852, 1692953, 1693415 .....	1650502		6422BR
<b>2825H; 2827H</b>			
Drive .....	1721393		6710BR
Primary; W/50" Deck .....	1707740		6869
Primary; W/54" Deck .....	1722039		6525BR
Secondary; W/50" Deck .....	1703836		6524BR
Secondary; W/54" Deck .....	1671076		6765BR
<b>2920H</b>			
P.T.O.; W/23" Wheels; Mfr. No. 1693132 .....	1716996		②6836
P.T.O.; W/26" Wheels; Mfr. No. 1693220 .....	1716996		②6836
<b>2920H LC</b>			
P.T.O.; Mfr. No. 1693136 .....	1716995		②6836
<b>2923H</b>			
P.T.O.; W/26" Wheels; Mfr. No. 1693770 .....	1716996		②6836
<b>2924D</b>			
P.T.O.; Mfr. No. 1693138 .....	1718602		②6834
<b>2925H</b>			
P.T.O.; Mfr. No. 1693134, 1693563 .....	1716996		②6836
<b>2927H; 2927LC</b>			
Lower Drive; W/60" Deck .....	1725154		6756BR
Upper Drive; W/48" Deck .....	1601672		6799BR
<b>Express</b>			
Drive; W/14.5 H.P. Eng.; Mfr. No. 1693452 .....	1665450		6627BR
Drive; W/15 H.P. Eng.; Mfr. No. 1693458 .....	1717397		6798BR
Drive; W/17 H.P. Eng.; Mfr. No. 1693525 .....	1717397		6798BR
<b>MF5</b>			
Blade .....	523733M1		6836
Mower .....	523734M1		6858
<b>MF6</b>			
Blade .....	523733M1		6836
<b>MF7</b>			
Deck .....	518125M1		6840
Main Drive .....	518223M1		6828
<b>MF7E</b>			
Main Drive .....	1023850M1		6935
<b>MF8</b>			
Deck .....	518125M1		6840
J.S. ....	511277M3		6850
Main Drive .....	518223M1		6828
Trans.; W/50" Belt O.C. ....	511277M3		6850
Trans.; W/77" Belt O.C. ....	519958M1		6877
<b>MF8E</b>			
J.S. ....	1023886M1	3620	6962
Main Drive; Ser. No. 6000 & Before .....	1023850M1		6935
Main Drive; Ser. No. 6001 & After .....	1030063M1	3330	6933
Starter/Gen. ....	1025796M1	1330	6733
<b>MF10</b>			
J.S. To Deck .....	511277M2		6850
P.T.O. ....	514132M1		6830
Starter/Gen. ....	511485M1	7320	

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MASSEY FERGUSON - Continued</b>			
<b>MF12; MF12G</b>			
Eng. To J.S. ....	514132M1		6830
J.S. To Deck .....	511277M2		6850
Main Drive .....	514891M1		AX80
P.T.O. ....	514132M1		6830
Starter/Gen. ....	511485M1	7320	
<b>MF85</b>			
Traction .....	3021251M1		6887
<b>MF626</b>			
Blade .....	523733M1		6836
<b>MF832</b>			
Trans. ....	530669M1		6837
<b>MF1200; MF1620; MF1650; MF1655</b>			
Blade .....	3020167M2		6386
<b>ZT</b>			
Drive; W/14 H.P. Eng.; Mfr. No. 1693471 .....	1719381		6838
Drive; W/16 H.P. Eng.; Mfr. No. 1693477 .....	1719381		6838
Drive; W/18 H.P. Eng.; Mfr. No. 1693234 .....	1719381		6838
<b>ZT29</b>			
Fan .....		9400	9400HD
<b>MAUSFIERES-SWITZERLAND</b>			
<b>135-420</b>			
Variator To Trans. ....	7540136		6931
<b>135-430</b>			
Blade .....	7540127		6966
Variator To Trans. ....	7540136		6931
<b>MAXIM</b>			
<b>30" Front Cut Mower</b>			
Blade; W/8 H.P. Eng. ....	272224		6853
Idler; W/8 H.P. Eng. ....	272223		6864
<b>42" Front Cut Mower</b>			
Belt; W/56" Belt O.C.; W/12, 15 H.P. Eng. ....	272222		6856
Belt; W/57" Belt O.C.; W/12, 15 H.P. Eng. ....	272236		6957
Belt; W/67" Belt O.C.; W/12, 15 H.P. Eng. ....	272235		6967
Belt; W/88" Belt O.C.; W/12, 15 H.P. Eng. ....	272234		6988
<b>42" Rear Eng. Rider</b>			
Eng. To Deck; W/12 H.P. Eng. ....			6957
<b>3070T</b>			
Drive .....	320272204		6838
<b>GL12F4281C</b>			
Belt; W/57" Belt O.C. ....	272236		6957
Belt; W/67" Belt O.C. ....	272235		6967
Transaxle .....	272234		6988
<b>GL830BE1C</b>			
Transaxle .....	272216		6831
<b>GL1230BETC12</b>			
Eng. To Deck .....	272217		6876
<b>M3010; M3080B</b>			
Belt; W/31" Belt O.C. ....	320272216		6831
Belt; W/76" Belt O.C. ....	320272217		6876
<b>Roof</b>			
Trans. ....	272237		6840
<b>MCCULLOCH</b>			
<b>MC30</b>			
Deck Drive .....	532441597		6976BR
<b>MC195H42LT</b>			
Deck Drive .....	532429636		6653BR
Drive .....	532130969		6757BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MCCULLOCH - Continued</b>			
<b>MC2042YT</b>			
Deck Drive .....	532429636		6653BR
Drive .....	532194346		6765BR
<b>MC13538LT</b>			
Deck Drive .....	532193214		6713BR
Drive .....	532138255		6758BR
<b>MC18542LT</b>			
Deck Drive .....	532144959		6758BR
Drive .....	532138255		6758BR
<b>MIDDLESWORTH</b>			
<b>72R</b>			
Front Mower; W/18 H.P. Eng. ....	10561		6876
Primary J.S.; W/18 H.P. Eng. ....	10560		6935
Rear Mower; W/18 H.P. Eng. ....	10562		6829
Trans.; W/18 H.P. Eng. ....	10563		6841
<b>C11B; C12K</b>			
Blade .....			6854
Eng. To Shaft .....			6930
Shaft To Deck .....			6869
Trans. ....			6848
<b>C54R</b>			
Blade .....			AX105
Deck Drive .....			AX105
<b>MONO</b>			
<b>DR-247B; DR-247BE</b>			
Belt .....	G158		6831
<b>M-368-E</b>			
Blade .....	368333		6870
Front Drive .....	368318		6835
Rear Drive .....	368319		6838
<b>R4; SR-245B; SR-245BE</b>			
Belt .....	G158		6831
<b>MONTGOMERY WARD</b>			
<b>8-36557; 8-36566X31</b>			
Blade .....	37X43		6601BR
Variator .....	37X45		6490BR
<b>9-30533</b>			
Deck .....	37X57		6498BR
Traction .....	37X38		6425BR
<b>3760-0; 3770-0</b>			
Blade .....	165179		6978
Clutch .....	165168		6837
<b>33010; 33020; 33028; 33029; 33030; 33035;</b>			
<b>33040</b>			
Clutch .....	11901		6836
P.T.O. ....	11943	3350	6935
<b>33043</b>			
Eng. To P.T.O. ....	11943	3350	6935
<b>33045</b>			
Clutch .....	11901		6836
P.T.O. ....	11943	3350	6935
<b>33047; 33048; 33050</b>			
Eng. To P.T.O. ....	11943	3350	6935
<b>33130; 33135; 33144; 33145; 33148B; 33149;</b>			
<b>33153; 33154; 33155; 33156</b>			
Clutch .....	11901		6836
P.T.O. ....	11943	3350	6935
<b>33157</b>			
Clutch .....	11901		6836
P.T.O. ....	11943	3350	6935
<b>33160</b>			
Eng. To P.T.O. ....	11943	3350	6935
<b>33162; 33180</b>			
Clutch .....	11901		6836
P.T.O. ....	11943	3350	6935



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>33185A; 33185B</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>33190</b>			
Clutch .....	11901		6836
P.T.O. ....	11943	3350	6935
<b>33200R; 33205; 33206</b>			
Blade .....	11792		6996
Deck .....	12684		6996
P.T.O. ....	11943		6935
Trans. ....	11901		6836
<b>33300; 33301; 33302; 33303</b>			
P.T.O. ....	170921		6824
<b>33332A; 33332B; 33332C</b>			
Blade .....	7540181		7014BR
Trans. ....	7540180		6510BR
<b>34500A; 34501A; 34502A</b>			
Blade .....	7540208		6855
Drive .....	7540207		6842
<b>34504; 34505</b>			
Blade .....	165184		6855
<b>34508</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>35101A; 35101B; 35102A; 35102B</b>			
Blade .....	7540188		6951
Eng. To Variator .....	7540187	3240	
Variator To Trans. ....	7540136		6931
<b>GIL84A</b>			
Eng. To Deck .....	14365		A49
Traction .....	13487	2370	6837
<b>GIL90A</b>			
Eng. To Deck .....	17518		6960
Traction .....	13487	2370	6837
<b>GIL99A</b>			
Eng. To Deck .....	13560		6859
Traction .....	13487	2370	6837
<b>GIL1280A; GIL1280S; GIL1281A; GIL1281R</b>			
Drive .....	11144		6835
Trans. ....			6852
<b>GIL33010A; GIL33011A; GIL33020A;</b> <b>GIL33020B; GIL33020C; GIL33028A;</b> <b>GIL33029A; GIL33029B; GIL33030A;</b> <b>GIL33030B</b>			
Hyd. Lift .....	12023		6721
P.T.O. ....	11943	3350	6935
Trans. ....	11901		6836
<b>GIL33035A; GIL33035B; GIL33040A;</b> <b>GIL33040B; GIL33041A; GIL33042A;</b> <b>GIL33043A; GIL33044A; GIL33045A;</b> <b>GIL33045B</b>			
Hyd. Lift .....	12023		6721
P.T.O. ....	11943	3350	6935
Trans. ....	11901		6836
<b>GIL33047A; GIL33047B; GIL33048B;</b> <b>GIL33050A; GIL33135A; GIL33140A;</b> <b>GIL33148A; GIL33148AZ; GIL33148B;</b> <b>GIL33148BZ</b>			
Hyd. Lift .....	12023		6721
P.T.O. ....	11943	3350	6935
Trans. ....	11901		6836
<b>GIL33148Z; GIL33162A; GIL33162B;</b> <b>GIL33180A; GIL33181A; GIL33182A;</b> <b>GIL33183A; GIL33184A; GIL33185A;</b> <b>GIL33186A</b>			
Hyd. Lift .....	12023		6721
P.T.O. ....	11943	3350	6935
Trans. ....	11901		6836

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>GIL33187A; GIL33188A; GIL33189A;</b> <b>GIL33190A; GIL33416A; GIL33417A;</b> <b>GIL33418A; GIL33419A; GIL33420A;</b> <b>GIL33421A</b>			
Hyd. Lift .....	12023		6721
P.T.O. ....	11943	3350	6935
Trans. ....	11901		6836
<b>GIL33490A</b>			
Blade .....	36770		6835
Trans. ....	200804		6874
<b>GIL33858</b>			
Blade .....	36806		6953
Eng. To Deck .....	11793		6989
<b>GIL33867; GIL33889</b>			
Eng. To J.S. ....	210752		6870
J.S. To Hydro. ....	210753		6831
<b>Lawn Trac</b>			
Belt; W/27" Belt O.C. ....	165132		6827
Belt; W/35" Belt O.C. ....	165133		6835
<b>MID5824 Chor Trac; MID5824B Chor Trac</b>			
Belt; W/32" Belt O.C. ....	503832	2320	6832
Belt; W/39" Belt O.C. ....	503839	2390	6839
<b>MID5848A Chor Trac; MID5849A Power Trac</b>			
Belt; W/3.6 H.P. Eng. ....	504253	3530	6953
Belt; W/6.8 H.P. Eng. ....	504251	3510	6951
<b>SIM1201</b>			
Drive .....	154273		6942
P.T.O. ....	154307		6835
Starter/Gen. ....	122060		6736
<b>SIM1210; SIM1211</b>			
Belt .....	121228		6837
P.T.O. ....	121216		6838
<b>SIM1216</b>			
Belt .....	108248		6848
<b>SIM1240</b>			
Drive .....	154273		6942
P.T.O. ....	106390		6836
Starter/Gen. ....	122146		6738
<b>SIM1242; SIM1243</b>			
Eng. To Countershaft .....	156231		6842
Gen. ....	122120		6734
Trans. ....	156120		6863
<b>SIM1265</b>			
Cross Deck .....	108099		6844
Drive .....	152017		B42
P.T.O. ....	154307		6835
Spindle .....	108209		6415BR
<b>SIM1271; SIM1274</b>			
Drive .....	152017		B42
P.T.O. ....	154307		6835
<b>SIM1442</b>			
Drive .....	121228		6837
P.T.O. ....	121216		6838
<b>SIM33300A; SIM33301A; SIM33302A;</b> <b>SIM33303A</b>			
Main Drive .....	170921		6824
<b>Speed Rider</b>			
Trans.; W/5 H.P. Eng. ....	165142		6841
<b>TM34513; TM34513A; TM34513B</b>			
Blade .....	7540208		6855
Drive .....	7540207		6842
<b>TMO61C</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>TMO1375A; TMO1377A</b>			
Blade .....	754113	3480	6948
Drive .....	754112	3800	6980

Lawn & Garden Equipment

RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>TMO1448B</b>			
Drive .....	7540157		6928
Trans. ....	7540136		6931
<b>TMO19846</b>			
Blade .....	7540349		6637BR
Deck .....	7540350		6464BR
<b>TMO33331A</b>		3810	6981
Drive .....	7540182		
<b>TMO33331B</b>		3810	6981
Blade; W/81" Belt O.C. ....	7540182		7014BR
Blade; W/83" Belt O.C. ....	7540181		6510BR
Drive; W/54" Belt O.C. ....	7540180		6981
Drive; W/81" Belt O.C. ....	7540182	3810	
<b>TMO33332B; TMO33332C</b>		3810	6981
Blade; W/81" Belt O.C. ....	7540182		7014BR
Blade; W/83" Belt O.C. ....	7540181		6510BR
Drive .....	7540180		
<b>TMO33340A; TMO33350A</b>			6979
Drive .....	7540217		6979
Trans. ....	7540217		
<b>TMO33410A; TMO33411A</b>			6979
Drive .....	7540217		
<b>TMO33551; TMO33551A</b>			6859
Drive .....	7540245		6840
Trans. ....	7540244		
<b>TMO33554A</b>			6859
Blade .....	7540245		6832
Drive .....	7540177		
<b>TMO33559A</b>			6859
Drive .....	7540245		6840
Trans. ....	7540244		
<b>TMO33566</b>			6464BR
Blade .....	7540350		6637BR
Deck .....	7540349		6431BR
Variator .....	7540248		6431BR
Vari-Speed .....	7540248		
<b>TMO33810A; TMO33810B</b>			6961
Blade .....	7540203		6867
Trans. ....	7540204		
<b>TMO33811A; TMO33812A</b>			6961
Blade .....	7540203		6867
Trans. ....	165165		
<b>TMO33812B</b>			6961
Blade .....	7540203		6867
Trans. ....	7540204		
<b>TMO33813A</b>			6864
Deck .....	165166		6850
Drive; W/50" Belt O.C. ....	7540206		6867
Drive; W/67" Belt O.C. ....	7540204		6864
Trans. ....	7540204		6867
<b>TMO33813C</b>			6864
Deck .....	165166		6850
Drive; W/50" Belt O.C. ....	7540206		6867
Drive; W/67" Belt O.C. ....	7540204		6864
Eng. To Deck .....	165166		6867
Trans. ....	7540204		
<b>TMO33813D; TMO33813E</b>			6864
Deck .....	165166		6850
Drive; W/50" Belt O.C. ....	7540206		6867
Drive; W/67" Belt O.C. ....	7540204		
<b>TMO33814A</b>			6864
Deck .....	165166		6850
Drive; W/50" Belt O.C. ....	7540206		6867
Drive; W/67" Belt O.C. ....	7540204		6867
Trans. ....	7540204		
<b>TMO33814C</b>			6864
Deck .....	165166		6850
Drive; W/50" Belt O.C. ....	7540206		

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>TMO33814C - Continued</b>			
Drive; W/67" Belt O.C. ....	7540204		6867
Eng. To Deck .....	165166		6864
Trans. ....	7540204		6867
<b>TMO33815; TMO33815A; TMO33815B;</b>			
<b>TMO33815C; TMO33815D; TMO33815E;</b>			
<b>TMO33815F; TMO33816A</b>			6854
Blade .....	7540195		6451BR
Drive .....	7540198		
<b>TMO33817X</b>		3500	6950
Blade .....	7540138		6451BR
Drive .....	7540198		
<b>TMO33818A; TMO33819A</b>			6488BR
Deck .....	7540145		6937
Trans.; W/37" Belt O.C. ....	7540173		6865
Trans.; W/65" Belt O.C. ....	7540191		
<b>TMO33839A</b>		3500	6950
Blade .....	7540138		6451BR
Drive .....	7540198		
<b>TMO33840A; TMO33841A</b>		3500	6967
Blade .....	7540151		6950
Drive .....	7540138		6931
Trans. ....	7540136		
<b>TMO33842C; TMO33843</b>			6488BR
Blade .....	7540145		6511BR
Clutch .....	7540226		
<b>TMO33844A</b>			6551BR
Drive .....	7540226		
<b>TMO33846A; TMO33846B</b>			6864
Deck .....	165166		6850
Drive; W/50" Belt O.C. ....	7540206		6867
Drive; W/67" Belt O.C. ....	7540204		
<b>TMO33847; TMO33847A</b>			6964
Blade .....	7540167		6451BR
Clutch .....	7540198		
<b>TMO33853</b>			6967
Blade .....	7540151		6865
Trans. ....	7540191		
<b>TMO33854</b>			6964
Blade .....	7540167		6451BR
Clutch .....	7540198		
<b>TMO33855A</b>		3500	6967
Blade .....	7540151		6950
Drive .....	7540138		6931
Trans. ....	7540136		
<b>TMO33856A</b>			6864
Blade .....	1651066		6867
Drive .....	7540204		6850
Spindle .....	7540206		
<b>TMO33860; TMO33860B; TMO33860C;</b>			6488BR
<b>TMO33861</b>			6551BR
Blade .....	7540145		
Clutch .....	7540226		
<b>TMO33864A</b>			6964
Blade .....	7540167		6451BR
Drive .....	7540198		
<b>TMO33866A</b>			6964
Blade .....	7540167		6451BR
Clutch .....	7540198		6488BR
Drive .....	7540145		
<b>TMO33876; TMO33876A</b>			6967
Blade .....	7540151		6775BR
Clutch .....	7540266		
<b>TMO33886</b>			6488BR
Blade .....	7540145		6551BR
Clutch .....	7540226		



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>TMO33886C</b>			
Variator .....	7540266		6775BR
<b>TMO33900A</b>			
Blade; W/38" Belt O.C. ....	7540240		6511BR
Blade; W/47" Belt O.C. ....	7540290		6847
Blade; W/63" Belt O.C. ....	7540347		6847BR
Deck .....	7540347		6847BR
Drive; W/35" Belt O.C. ....	7540241		6494BR
Drive; W/38" Belt O.C. ....	7540240		6511BR
Variator; W/35" Belt O.C. ....	7540241		6494BR
Variator; W/38" Belt O.C. ....	7540240		6511BR
<b>TMO33901; TMO33901A</b>			
Blade .....	7540271		6557BR
Clutch .....	7540266		6775BR
<b>TMO33902</b>			
Blade .....	7540145		6488BR
Clutch .....	7540226		6551BR
<b>TMO33902A</b>			
Variator .....	7540266		6775BR
<b>TMO33903</b>			
Blade .....	7540145		6488BR
Clutch .....	7540226		6551BR
<b>TMO33904; TMO33904A</b>			
Blade .....	7540271		6557BR
Clutch .....	7540266		6775BR
<b>TMO33905</b>			
Variator .....	7540266		6775BR
<b>TMO33905A</b>			
Blade .....	7540329		6630BR
<b>TMO33906A</b>			
Variator .....	7540266		6775BR
<b>TMO33907A</b>			
Blade .....	7540145		6488BR
<b>TMO33907B</b>			
Deck .....	7540145A		6488BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>TMO33908A</b>			
Belt; W/52" Belt O.C. ....	7540229		6852
Belt; W/74" Belt O.C. ....	7540293		6501BR
<b>TMO33909A</b>			
Blade .....	7540145		6488BR
Clutch .....	7540226		6551BR
<b>TMO33909B</b>			
Deck .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>TMO33912A</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540266		6775BR
Variator To Trans. ....	7540268		6951
<b>TMO33913A</b>			
Blade .....	7540145		6488BR
<b>TMO33914A</b>			
Blade .....	7540271		6557BR
<b>TMO33916A; TMO33917A</b>			
Blade .....	7540329		6630BR
<b>TMO33918A</b>			
Deck .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>TMO33919A; TMO33919B</b>			
Deck; W/32" Deck .....	7540342		6868
<b>TMO33920A; TMO33920B; TMO33921A;</b>			
<b>TMO33921B; TMO33922A</b>			
Blade .....	7540329		6630BR
<b>TMO33924A; TMO33924B</b>			
Blade .....	7540329		6630BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>TMO33924A; TMO33924B - Continued</b>			
Deck .....	7540329		6630BR
<b>TMO33925A; TMO33927A; TMO33929A;</b>			
<b>TMO33931A; TMO33932A</b>			
Blade .....	7540329		6630BR
<b>TMO33934A</b>			
Blade .....	7540329		6630BR
Deck .....	7540329		6630BR
<b>TMO33936A</b>			
Belt; W/52" Belt O.C. ....	7540229		6852
Belt; W/74" Belt O.C. ....	7540293		6501BR
<b>TMO033936A</b>			
Blade .....	7540229		6852
Deck .....	7540293		6501BR
<b>TMO34500A; TMO34500B; TMO34500C;</b>			
<b>TMO34500D; TMO34501A; TMO34502A</b>			
Blade .....	7540208		6855
Drive .....	7540207		6842
<b>TMO34506A; TMO34507A; TMO34507B</b>			
Blade .....	7540198		6451BR
Drive .....	7540207		6842
<b>TMO34508A</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>TMO34509A</b>			
Blade .....	7540208		6855
Drive .....	7540207		6842
<b>TMO34514A; TMO34514B</b>			
Blade .....	7540198		6451BR
Drive .....	7540207		6842
<b>TMO34517A</b>			
Blade .....	7540188		6951
Eng. To Variator .....	7540187	3240	6924
Variator To Trans. ....	7540136		6931
<b>TMO34524; TMO34527A</b>			
Blade .....	7540198		6451BR
Drive .....	7540207		6842
<b>TMO34528; TMO34530; TMO34535A;</b>			
<b>TMO34538; TMO34538A</b>			
Blade .....	7540264		6639BR
Clutch .....	7540241		6494BR
Eng. To Deck .....	7540240		6511BR
<b>TMO34538B</b>			
Blade .....	7540264		6639BR
Clutch .....	7540241		6494BR
Deck Drive .....	7540291		6641BR
Eng. To Deck .....	7540240		6511BR
Eng. To Variator .....	7540241		6494BR
Variator .....	7540240		6511BR
<b>TMO34538C</b>			
Blade .....	7540264		6639BR
Clutch .....	7540241		6494BR
Eng. To Deck .....	7540240		6511BR
<b>TMO34540</b>			
Blade .....	7540250	2530	6853
Clutch .....	7540241		6494BR
Eng. To Deck .....	7540240		6511BR
<b>TMO35101; TMO35102</b>			
Blade .....	7540188		6951
Eng. To Variator .....	7540187	3240	6924
Variator To Trans. ....	7540136		6931
<b>TMO134502; TMO134504; TMO134506;</b>			
<b>TMO134512; TMO134514; TMO134515;</b>			
<b>TMO134518</b>			
Variator; W/35" Belt O.C. ....	7540241		6494BR
Variator; W/38" Belt O.C. ....	7540240		6511BR
<b>TMO134618</b>			
Drive .....	7540268		6951

Lawn & Garden Equipment

RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>TMO134619</b>			
Blade .....	7540271		6557BR
Drive .....	7540266		6775BR
<b>TMO134638; TMO134668; TMO134698</b>			
Drive .....	7540268		6951
<b>TMO138693</b>			
Belt; W/52" Belt O.C. ....	7540229		6852
Belt; W/74" Belt O.C. ....	7540293		6501BR
<b>TMO139758</b>			
Blade .....	7540350		6464BR
Deck .....	7540349		6637BR
Variator .....	7540248		6431BR
Vari-Speed .....	7540248		6431BR
<b>TMO190846</b>			
Blade .....	7540349		6637BR
Deck .....	7540350		6464BR
<b>TMO668088</b>			
Blade .....	7540329		6630BR
<b>TMR91A; TMR98A</b>			
Belt .....			6837
<b>TMR8175</b>			
Belt; W/28" Belt O.C. ....		2280	6828
Belt; W/30" Belt O.C. ....		②2300	②6830
<b>TMR8176</b>			
Belt; W/29" Belt O.C. ....		2290	6829
Belt; W/33" Belt O.C. ....		2330	6833
Belt; W/47" Belt O.C. ....		2470	6847
<b>TMR8177A</b>			
Belt; W/47" Belt O.C. ....		2470	6847
<b>TMR8191A</b>			
Belt; W/29" Belt O.C. ....			6829
Belt; W/33" Belt O.C. ....			6833
<b>TMR8192A; TMR8192B</b>			
Belt .....			6833
<b>TMR8193A</b>			
Belt .....			6837
<b>WFH46A; WFH48A</b>			
Blade .....		②1230	②6723
Trans. ....		2480	6848
<b>ZHJ-UT32016A; ZHJ-UT32017A; ZHJ-UT32018A</b>			
Blade .....	JA991488		6873
Trans. ....	JA990738		6852
<b>ZHJ-UT33009</b>			
Blade .....	JA992251		6864
<b>ZHJ-UT-33009</b>			
Trans. ....		2480	6848
<b>ZHJ-UT33010</b>			
Blade .....	JA992251		6864
<b>ZHJ-UT-33010</b>			
Trans. ....		2480	6848
<b>ZMH8-36557; ZMH8-36566</b>			
Blade .....	37X43		6601BR
<b>ZMH9-38600</b>			
Deck .....	37X57		6498BR
Traction .....	37X38		6425BR
<b>ZMH33910</b>			
Deck .....	37X57		6498BR
Traction; W/40" Belt O.C. ....	37X38		6425BR
Traction; W/95" Belt O.C. ....	37X61		6452BR
<b>ZMH33915</b>			
Blade .....	37X43		6601BR
Variator .....	37X45		6490BR
<b>ZMH-36568</b>			
Blade .....	37X43		6601BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>ZMH836566; ZMH836568</b>			
Blade .....	37X43		6601BR
Variator .....	37X45		6490BR
<b>ZMH938600</b>			
Traction .....	37X61		6452BR
<b>ZUJ94</b>			
Blade .....	165179		6978
Clutch .....	165168		6837
<b>ZYJ48A; ZYJ48B; ZYJ50A; ZYJ50B</b>			
Blade .....	165183		6857
Trans. ....	165181		6839
<b>ZYJ68A; ZYJ69A; ZYJ75A; ZYJ75C</b>			
Blade .....	165143		6856
Drive .....	165142		6841
<b>ZYJ76A</b>			
Drive; W/40" Belt O.C. ....	165138		6840
Drive; W/56" Belt O.C. ....	165139		6856
<b>ZYJ76B</b>			
Blade .....	165143		6856
Drive .....	165142		6841
<b>ZYJ77A; ZYJ77B</b>			
Drive; W/40" Belt O.C. ....	165138		6840
Drive; W/56" Belt O.C. ....	165139		6856
<b>ZYJ77C; ZYJ77D; ZYJ78A; ZYJ79A</b>			
Blade .....	165143		6856
Drive .....	165142		6841
<b>ZYJ80; ZYJ81</b>			
Blade .....	165169		6855
Clutch .....	165168		6837
<b>ZYJ82A</b>			
Blade .....	165184		6855
<b>ZYJ83A; ZYJ83C</b>			
Blade .....	165143		6856
Drive .....	165142		6841
<b>ZYJ86A</b>			
Blade .....	165184		6855
<b>ZYJ87A; ZYJ87B</b>			
Blade .....	165143		6856
Clutch .....	165160		6840
<b>ZYJ87C</b>			
Blade .....	165182		6854
Trans. ....	165181		6839
<b>ZYJ87D</b>			
Blade .....	165143		6856
Trans. ....	165181		6839
<b>ZYJ88; ZYJ89</b>			
Blade .....	165140		6956
Clutch .....	165141		6840
Eng. To Deck .....	165130		6829
<b>ZYJ91</b>			
Blade .....	165169		6855
Clutch .....	165168		6837
<b>ZYJ93; ZYJ95A</b>			
Blade .....	165159		6858
Clutch .....	165160		6840
<b>ZYJ96A</b>			
Mower Drive .....	165171		6963
Trans. ....	165168		6837
<b>ZYJ97</b>			
Clutch .....	165164		6839
<b>ZYJ1370; ZYJ1372; ZYJ1378</b>			
Blade .....	41969		6950
Clutch .....	41980		6867
Eng. To Deck .....	41993		6859
<b>ZYJ1387</b>			
Blade .....	165161		6961

②Two Required





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>ZYJ1387 – Continued</b>			
Clutch .....	165151		6863
<b>ZYJ1388</b>			
Blade .....	41969		6950
Clutch; W/64" Belt O.C. ....	165154		6864
Clutch; W/67" Belt O.C. ....	41980		6867
Eng. To Deck; W/59" Belt O.C. ....	41993		6859
Eng. To Deck; W/62" Belt O.C. ....	165153		6862
<b>ZYJ1390; ZYJ1394</b>			
Blade .....	165161		6961
Clutch .....	165151		6863
<b>ZYJ1394C</b>			
Blade .....		3600	6960
<b>ZYJ1395; ZYJ1396; ZYJ1397</b>			
Blade .....	165161		6961
Clutch .....	165151		6863
<b>ZYJ1398</b>			
Blade .....	41969		6950
Clutch .....	41980		6867
Eng. To Deck; W/59" Belt O.C. ....	41993		6859
Eng. To Deck; W/62" Belt O.C. ....	165153		6862
<b>ZYJ1399; ZYJ1399A</b>			
Blade .....	41969		6950
Clutch .....	165154		6864
Eng. To Deck .....	165153		6862
<b>ZYJ1400 Hydro</b>			
Blade .....	165161		6961
Clutch .....	165163		6865
<b>ZYJ1405; ZYJ1408</b>			
Blade .....	165161		6961
Clutch .....	165165		6867
<b>ZYJ1410A Hydro</b>			
Blade .....	165173		6963
Clutch .....	165163		6865
<b>ZYJ1410B Hydro</b>			
Blade .....	165161		6961
Clutch .....	165163		6865
<b>ZYJ1414A</b>			
Mower Deck .....	165175		6945
Mower Drive .....	165174		6948
<b>ZYJ1415</b>			
Clutch .....	165172		6867
<b>ZYJ1428; ZYJ1430</b>			
Blade .....	165161		6961
Clutch .....	165165		6867
<b>ZYJ1433</b>			
Blade .....	165167		6951
Clutch .....	165172		6867
Eng. To Deck .....	165166		6864
<b>ZYJ1434</b>			
Blade .....	165161		6961
Clutch .....	165165		6867
<b>ZYJ1439</b>			
Clutch .....	165172		6867
<b>ZYJ1450</b>			
Blade .....	165161		6961
Clutch .....	165165		6867
<b>ZYJ3720-1; ZYJ3720-2; ZYJ3730-1;</b>			
<b>ZYJ3730-2</b>			
Blade .....	165183		6857
Trans. ....	165181		6839
<b>ZYJ3760-0; ZYJ3770-0</b>			
Blade .....	165179		6978
Clutch .....	165168		6837
<b>ZYJ33800; ZYJ33801</b>			
Blade .....	165161		6961
Clutch .....	165165		6867

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>ZYJ33808</b>			
Blade .....	165167		6951
Clutch .....	165172		6867
Eng. To Deck .....	165166		6864
<b>ZYJ33809</b>			
Blade .....	165174		6948
Clutch .....	165172		6867
Eng. To Deck .....	165175		6945
<b>ZYJ34504A; ZYJ34505A</b>			
Blade .....	165184		6855
<b>MOTO-MOWER</b>			
<b>26-300</b>			
Belt .....	1008838	1285	
<b>26-302</b>			
Belt; W/25" Belt O.C. ....	4468	2250	6825
Belt; W/29" Belt O.C. ....	1032290		6829
<b>61-300 24"</b>			
Belt .....	1008838	1285	
<b>61-302</b>			
Belt; W/25" Belt O.C. ....	1004468	2250	6825
Belt; W/29" Belt O.C. ....	1032290		6829
<b>61-302 24"</b>			
Belt; W/25" Belt O.C. ....	4468	2250	6825
Belt; W/29" Belt O.C. ....	1032290		6829
<b>306; 320</b>			
Belt; W/25" Belt O.C. ....	1004468	2250	6825
Belt; W/29" Belt O.C. ....	1032290		6829
<b>322; 323</b>			
Belt .....	1032290		6829
<b>331</b>			
Belt; W/25" Belt O.C. ....	1004468	2250	6825
Belt; W/29" Belt O.C. ....	1032290		6829
<b>6000; 6001</b>			
High Speed Drive .....	1022480		6831
Low Speed Drive .....	1022149		6832
Transaxle .....	1022460	2600	6860
<b>6007; 6008</b>			
Belt; W/35" Belt O.C. ....	1034685	3350	6935
Belt; W/62" Belt O.C. ....	1034684	3620	6962
<b>6024; 6025</b>			
Eng. To J.S. ....	1040576	3330	6933
Gen. ....	1048684	7360	
Transaxle .....	1034684	3620	6962
<b>7000; 8000</b>			
Belt; W/35" Belt O.C. ....	1034685	3350	6935
Belt; W/62" Belt O.C. ....	1034684	3620	6962
<b>Deluxe 302 24"; Deluxe 304 24"</b>			
Belt; W/25" Belt O.C. ....	4468	2250	6825
Belt; W/29" Belt O.C. ....	1032290		6829
<b>Moto Boy</b>			
Belt .....	1008838	1285	
<b>Roto Ride 24"</b>			
Belt; W/23" Belt O.C. ....			6823
Belt; W/27" Belt O.C. ....			6827
Belt; W/29" Belt O.C. ....	1032290		6829
<b>Squire 22"</b>			
Belt .....	4533	2330	6833
<b>Super 26-302</b>			
Belt; W/25" Belt O.C. ....	1004468	2250	6825
Belt; W/29" Belt O.C. ....	1032290		6829
<b>Super 1900-14</b>			
Belt .....	1008838	1285	
<b>MTD GOLD</b>			
<b>13AP925P004</b>			
Deck Drive .....	954-04077		6778BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD GOLD - Continued</b>			
<b>13AP925P004 – Continued</b>			
Trans .....	954-04207		6879
<b>13AX771S004</b>			
Deck Drive .....	954-04060B		6776BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-0241A		6494BR
<b>13AX795S004</b>			
Deck Drive .....	954-04060B		6776BR
Drive .....	95404252		6884
<b>13AX915T004</b>			
Deck Drive .....	95404219		6651BR
Trans .....	954-04207		6879
<b>17AF2ACK004</b>			
Deck Drive .....	954-04138A		6783BR
Trans .....	95404043A	2580	
<b>17AF2ACP004</b>			
Deck Drive .....	954-04044A		6842BR
Trans .....	95404043A	2580	
<b>17AF2ACS004</b>			
Deck Drive .....	954-04137A		6684BR
Trans .....	95404043A	2580	
<b>MTD PRODUCTS, INC.</b>			
<b>3Z457</b>			
Blade .....	7540167		6964
Trans .....	7540164	2630	6863
<b>3Z459</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>3Z459A; 3Z459B; 3Z459C</b>			
Blade .....	7540145		6488BR
Trans.; W/37" Belt O.C. ....	7540173	3370	6937
Trans.; W/65" Belt O.C. ....	7540191		6865
Trans.; W/82" Belt O.C. ....	7540226		6551BR
<b>3Z460</b>			
Blade .....	7540178	3820	6982
Trans.; W/48" Belt O.C. ....	7540200		6848
Trans.; W/50" Belt O.C. ....	7540179		6950
<b>3Z464</b>			
Blade .....	7540198		6451BR
Trans .....	7540207		6842
<b>3Z523</b>			
Gen. ....	7540169		3V355
P.T.O. ....	7540165		6834
<b>3Z526</b>			
Blade .....	7540184		6852
Eng. To Deck .....	7540180		6510BR
Trans .....	7540182	3810	6981
<b>3Z588</b>			
Drive .....	7540218		6959
P.T.O. ....	7540214		6850
Trans .....	7540211		6946
<b>9-5165</b>			
Blade .....	7540107		6830
Trans .....	7540936		6847
<b>9-5182; 9-5189</b>			
Drive .....	7540151		6967
<b>13A-45G; 13A-47G</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Variable Speed .....	7540281		6405BR
<b>13A-67A</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Variable Speed .....	7540370		6439BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13A-69A</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Trans .....	7540349		6637BR
<b>13A-325; 13A-328</b>			
Deck .....	7540754		6576BR
Variable Speed .....	7540453		6617BR
<b>13A-450; 13A-451; 13A-452; 13A-453</b>			
Deck; W/36" Deck .....	7540364		6482BR
Deck; W/38" Deck .....	7540329A		6630BR
Variable Speed .....	7540281		6405BR
<b>13A-455</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Variable Speed .....	7540281		6405BR
<b>13A-470; 13A-471; 13A-472; 13A-473;</b>			
<b>13A-475</b>			
Deck; W/36" Deck .....	7540364		6482BR
Deck; W/38" Deck .....	7540329A		6630BR
Variable Speed .....	7540281		6405BR
<b>13A-560</b>			
Deck .....	7540264		6639BR
Eng. ....	754-0241A		6494BR
Variable Speed .....	7540240		6511BR
<b>13A-604</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O.; W/42" Deck ...	7540472		6812BR
P.T.O.; W/Electric P.T.O.; W/46" Deck ...	7540474		6480BR
P.T.O.; W/Man. P.T.O.; W/42" Deck .....	7540485		6575BR
P.T.O.; W/Man. P.T.O.; W/46" Deck .....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13A-608</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/42" Deck .....	7540472		6812BR
P.T.O.; W/46" Deck .....	7540476		6416BR
Variable Speed .....	7540467		6606BR
<b>13A-614; 13A-619</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Trans .....	7540370		6439BR
<b>13A0619G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans .....	7540370		6439BR
<b>13A-660</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
Eng. ....	7540280A		6447BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Variable Speed .....	7540370		6439BR
<b>13A-661; 13A-662; 13A-663; 13A-665;</b>			
<b>13A-667; 13A-670; 13A-671; 13A-672;</b>			
<b>13A-673</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Variable Speed .....	7540370		6439BR
<b>13A0673G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>13A-674; 13A-675</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13A-674; 13A-675 - Continued</b>			
Variable Speed .....	7540370		6439BR
<b>13A0675H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13A-677; 13A-678; 13A-679</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Variable Speed .....	7540370		6439BR
<b>13A-690; 13A-693; 13A-694; 13A-695; 13A-698</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Trans. ....	7540349		6637BR
<b>13A0698G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13A-699</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Trans. ....	7540349		6637BR
<b>13A747GF</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>13A1674G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13A2695G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13A3662F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280A		6447BR
<b>13A4660F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>13A4662F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280A		6447BR
<b>13A4667F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>13A5450F; 13A5453F; 13A5470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>13A5660F</b>			
Eng. To Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13A5660G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13A5661F; 13A5665F</b>			
Eng. To Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13A5670G; 13A6660G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13A6665H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>13A6672G; 13A6673G</b>			
Eng. To V.S. ....	7540280A		6447BR
<b>13A-6675</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Variable Speed .....	7540370		6439BR
<b>13A6675G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13A6675H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>13A6693G; 13A6695G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13A6695H; 13A6698H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13A-6699</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Trans. ....	7540349		6637BR
<b>13A6699H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13A8673G; 13A8679G</b>			
Eng. To V.S. ....	7540280A		6447BR
<b>13A8693G</b>			
Trans. ....	7540441		6417BR
<b>13A8693H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>13A617</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540349		6637BR
P.T.O.; W/42" Deck .....	7540485		6575BR
P.T.O.; W/46" Deck .....	7540486		6502BR
<b>13AB560</b>			
Deck .....	7540264		6639BR
Eng. ....	754-0241A		6494BR
Variable Speed .....	7540240		6511BR
<b>13AB699H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AC450F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>13AD604</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O.; W/42" Deck ...	7540472		6812BR
P.T.O.; W/Electric P.T.O.; W/46" Deck ..	7540474		6480BR
P.T.O.; W/Man. P.T.O.; W/42" Deck .....	7540485		6575BR
P.T.O.; W/Man. P.T.O.; W/46" Deck .....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AD604G</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13AD604G – Continued</b>			
P.T.O. ....	7540474		6480BR
Variable Speed .....	7540467		6606BR
<b>13AD608</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/42" Deck .....	7540472		6812BR
P.T.O.; W/46" Deck .....	7540476		6416BR
Variable Speed .....	7540467		6606BR
<b>13AD624G</b>			
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
<b>13AD674</b>			
Deck; W/42" Deck .....	7540371A		6402BR
Variable Speed .....	7540370		6439BR
<b>13AD674G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>13AE450E</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>13AE450F; 13AE451F; 13AE470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>13AF560</b>			
Deck .....	7540264		6639BR
Eng. ....	754-0241A		6494BR
Variable Speed .....	7540240		6511BR
<b>13AF660G</b>			
Eng. To V.S. ....	7540280A		6447BR
<b>13AF695H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AG609G</b>			
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
Variable Speed .....	7540467		6606BR
<b>13AG619H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AG675</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Variable Speed .....	7540370		6439BR
<b>13AG675G; 13AG678G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AG679H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AG695</b>			
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Trans. ....	7540349		6637BR
<b>13AG695G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AG698H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13AG698H – Continued</b>			
Trans. ....	7540441		6417BR
<b>13AH450F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>13AH451E</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>13AH451F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>13AH471F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
V.S. To Trans. ....	7540281		6405BR
<b>13AH660</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Variable Speed .....	7540370		6439BR
<b>13AH660F</b>			
Eng. To Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280A		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AH661F</b>			
Eng. To Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AH662F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280A		6447BR
<b>13AH665F; 13AH667F; 13AH670F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>13AH672F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280A		6447BR
<b>13AI69AH</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AI607</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/42" Deck .....	7540485		6575BR
P.T.O.; W/46" Deck .....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AI607H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AI608G</b>			
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
P.T.O.; W/Man. P.T.O. ....	7540485		6575BR
Variable Speed .....	7540467		6606BR
<b>13AI608H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AI609H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
Variable Speed .....	7540467		6606BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13AI618H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AI673H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280A		6447BR
<b>13AI674G</b>			
Eng. To V.S. ....	7540280		6447BR
<b>13AI674H</b>			
Cross Deck .....	7540440		6477BR
<b>13AI675H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280A		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AI693H; 13AI695H; 13AI699H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AJ609H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
Variable Speed .....	7540467		6606BR
<b>13AJ693H; 13AJ694H; 13AJ695H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AJ699</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Trans. ....	7540349		6637BR
<b>13AJ699H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AK604</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O.; W/42" Deck ...	7540472		6812BR
P.T.O.; W/Electric P.T.O.; W/46" Deck ...	7540474		6480BR
P.T.O.; W/Man. P.T.O.; W/42" Deck .....	7540485		6575BR
P.T.O.; W/Man. P.T.O.; W/46" Deck .....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AK604G</b>			
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
P.T.O.; W/Man. P.T.O. ....	7540485		6575BR
Variable Speed .....	7540467		6606BR
<b>13AK608</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/42" Deck .....	7540472		6812BR
P.T.O.; W/46" Deck .....	7540476		6416BR
Variable Speed .....	7540467		6606BR
<b>13AK608G</b>			
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
P.T.O.; W/Man. P.T.O. ....	7540485		6575BR
Variable Speed .....	7540467		6606BR
<b>13AK660G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>13AK673G</b>			
Eng. To V.S. ....	7540280A		6447BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13AK693G</b>			
Trans. ....	7540441		6417BR
<b>13AK695H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AL450C</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>13AL452F; 13AL470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>13AL660F; 13AL667F</b>			
Eng. To Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AL670F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280A		6447BR
<b>13AL675F; 13AL677F</b>			
Eng. To Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AM47GF</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
V.S. To Trans. ....	7540281		6405BR
<b>13AM67AG</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AM69A</b>			
Trans. ....	7540349		6637BR
<b>13AM69AG</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AM475F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
V.S. To Trans. ....	7540281		6405BR
<b>13AM660F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280A		6447BR
<b>13AM660G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AM665G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280A		6447BR
<b>13AM667F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AM670G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280A		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AM672F</b>			
Eng. To Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AM672G; 13AM673G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280A		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AM675G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	9540280A		6447BR

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13AM675G – Continued</b>			
V.S. To Trans. ....	7540370		6439BR
<b>13AM678G</b>			
Eng. To V.S. ....	7540280A		6447BR
<b>13AM679G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AM690</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Trans. ....	7540349		6637BR
<b>13AM690G; 13AM693G; 13AM695G; 13AM698G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AN475F</b>			
V.S. To Trans. ....	7540281		6405BR
<b>13AN607H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AN659H</b>			
Cross Deck .....	7540440		6477BR
<b>13AN672F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>13AN673G</b>			
Eng. To V.S. ....	7540280A		6447BR
<b>13AN675G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280A		6447BR
<b>13AN678G</b>			
Eng. To V.S. ....	7540280A		6447BR
<b>13AN679G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280A		6447BR
<b>13AN690G; 13AN693G</b>			
Trans. ....	7540441		6417BR
<b>13AN693H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AN694G</b>			
Trans. ....	7540441		6417BR
<b>13AN695G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AN695H</b>			
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AN697G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AN698G</b>			
Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AN698H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AN699G</b>			
Trans. ....	7540441		6417BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13AO69AG</b>			
Cross Deck .....	7540440		6477BR
Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AO619</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Trans. ....	7540370		6439BR
<b>13AO619G</b>			
Eng. To V.S. ....	7540280		6447BR
<b>13AO663F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280A		6447BR
<b>13AO665G; 13AO670G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AO673H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AO675G</b>			
Eng. To V.S. ....	7540280A		6447BR
<b>13AO675H</b>			
Eng. To V.S. ....	7540280		6447BR
<b>13AO678H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AO695G; 13AO698G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AO699G</b>			
Trans. ....	7540441		6417BR
<b>13AQ607H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AQ609G</b>			
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
P.T.O.; W/Man. P.T.O. ....	7540485		6575BR
Variable Speed .....	7540467		6606BR
<b>13AQ665G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
<b>13AQ665H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AQ670G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>13AQ670H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AQ673G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13AQ675H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AQ695G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AQ695H; 13AQ698H; 13AQ699H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AR608G</b>			
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
Variable Speed .....	7540467		6606BR
<b>13AR698G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AS607H; 13AS608H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AS670G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>13AS673G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AS673H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>13AS675G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AS675H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280A		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AS679</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Variable Speed .....	7540370		6439BR
<b>13AS679G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AS693H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AS695G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AS695H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AS698G</b>			
Trans. ....	7540441		6417BR
<b>13AS699</b>			
Trans. ....	7540349		6637BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13AS699G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AS699H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AT608H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
Variable Speed .....	7540467		6606BR
<b>13AT618G</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
P.T.O.; W/Man. P.T.O. ....	7540485		6575BR
Variable Speed .....	7540467		6606BR
<b>13AT694G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AT694H</b>			
Trans. ....	7540441		6417BR
<b>13AU604</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O.; W/42" Deck ..	7540472		6812BR
P.T.O.; W/Electric P.T.O.; W/46" Deck ...	7540474		6480BR
P.T.O.; W/Man. P.T.O.; W/42" Deck .....	7540485		6575BR
P.T.O.; W/Man. P.T.O.; W/46" Deck .....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AU604H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O. ....	7540476		6416BR
Variable Speed .....	7540467		6606BR
<b>13AU607H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AU608H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
Variable Speed .....	7540467		6606BR
<b>13AU618H; 13AU624H</b>			
Cross Deck .....	7540349		6637BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
<b>13AU694H; 13AU695H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AV607H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
Variable Speed .....	7540467		6606BR
<b>13AV694G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AX604G</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O. ....	7540476		6416BR
Variable Speed .....	7540467		6606BR
<b>13AX604H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13AX604H – Continued</b>			
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13AX614</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Trans. ....	7540370		6439BR
<b>13AX614G; 13AX674G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>13AX675G</b>			
Eng. To V.S. ....	7540280A		6447BR
<b>13AX693G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AX694</b>			
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
<b>13AX694G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13AY609H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
Variable Speed .....	7540467		6606BR
<b>13AZ604H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O. ....	7540476		6416BR
Variable Speed .....	7540467		6606BR
<b>13B-325</b>			
Deck .....	7540754		6576BR
Variable Speed .....	7540453		6617BR
<b>13B-609</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O.; W/42" Deck ...	7540472		6812BR
P.T.O.; W/Electric P.T.O.; W/46" Deck ...	7540474		6480BR
P.T.O.; W/Man. P.T.O.; W/42" Deck .....	7540485		6575BR
P.T.O.; W/Man. P.T.O.; W/46" Deck .....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13BD604G</b>			
Drive .....	7540468		6556BR
Variable Speed .....	7540467		6606BR
<b>13BD609</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O.; W/42" Deck ...	7540472		6812BR
P.T.O.; W/Electric P.T.O.; W/46" Deck ...	7540474		6480BR
P.T.O.; W/Man. P.T.O.; W/42" Deck .....	7540485		6575BR
P.T.O.; W/Man. P.T.O.; W/46" Deck .....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13BD609G</b>			
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
P.T.O.; W/Man. P.T.O. ....	7540485		6575BR
Variable Speed .....	7540467		6606BR
<b>13BG698H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13BH660F; 13BH670F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280A		6447BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13BJ695H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13BK608G</b>			
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
Variable Speed .....	7540467		6606BR
<b>13BK695H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13BM675G</b>			
Eng. To V.S. ....	7540280A		6447BR
<b>13BM698G</b>			
Trans. ....	7540441		6417BR
<b>13BN673G</b>			
Eng. To V.S. ....	7540280A		6447BR
<b>13BN695G</b>			
Trans. ....	7540441		6417BR
<b>13BQ670G</b>			
Eng. To V.S. ....	7540280A		6447BR
<b>13BQ695H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13BR609G</b>			
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
P.T.O.; W/Man. P.T.O. ....	7540485		6575BR
Variable Speed .....	7540467		6606BR
<b>13BR698G</b>			
Trans. ....	7540441		6417BR
<b>13BS693H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13BU609H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13BX609G</b>			
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
P.T.O.; W/Man. P.T.O. ....	7540485		6575BR
Variable Speed .....	7540467		6606BR
<b>13BX614</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Deck; W/46" Deck .....	7540440		6477BR
P.T.O.; W/46" Deck .....	7540439		6406BR
Trans. ....	7540370		6439BR
<b>13BX614G</b>			
Eng. To Deck .....	7540371		6402BR
<b>13BX694G</b>			
Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>13BZ609</b>			
Deck; W/46" Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O.; W/42" Deck ...	7540472		6812BR
P.T.O.; W/Electric P.T.O.; W/46" Deck ...	7540474		6480BR
P.T.O.; W/Man. P.T.O.; W/42" Deck .....	7540485		6575BR
P.T.O.; W/Man. P.T.O.; W/46" Deck .....	7540486		6502BR
Variable Speed .....	7540467		6606BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>13BZ609H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540474		6480BR
P.T.O.; W/Man. P.T.O. ....	7540486		6502BR
Variable Speed .....	7540467		6606BR
<b>13CD609G</b>			
Drive .....	7540468		6556BR
P.T.O.; W/Electric P.T.O. ....	7540472		6812BR
Variable Speed .....	7540467		6606BR
<b>13CH660F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280A		6447BR
<b>14-360</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>14-410</b>			
Blade .....	7540138	3500	6950
<b>14-420; 14-430</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>14-460; 14-470</b>			
Blade .....	7540118		6963
Gen. ....	7540134	7330	
Trans. ....	7540937	3590	6959
<b>14A-82A; 14A-84A; 14A-820; 14A-823;</b>			
<b>14A-824; 14A-825; 14A-829</b>			
Deck; W/46" Deck .....	7540349		6637BR
Deck; W/50" Deck .....	7540291A		6641BR
P.T.O.; W/46" Deck .....	7540350		6464BR
P.T.O.; W/50" Deck .....	7540364		6482BR
Trans. ....	7540446		6605BR
<b>14A-833; 14A-834; 14A-835; 14A-839</b>			
Deck; W/46" Deck .....	7540349		6637BR
Deck; W/50" Deck .....	7540291A		6641BR
Eng. ....	7540461		6519BR
P.T.O.; W/46" Deck .....	7540350		6464BR
P.T.O.; W/50" Deck .....	7540364		6482BR
<b>14A-840; 14A-843; 14A-844; 14A-845;</b>			
<b>14A-849</b>			
Deck; W/46" Deck .....	7540349		6637BR
Deck; W/50" Deck .....	7540291A		6641BR
P.T.O.; W/46" Deck .....	7540350		6464BR
P.T.O.; W/50" Deck .....	7540364		6482BR
Trans. ....	7540446		6605BR
<b>14A9843H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
Eng. To V.S. ....	7540280		6447BR
<b>14AI825H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
<b>14AI825P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To Deck .....	7540364		6482BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540446		6605BR
<b>14AI828H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
<b>14AI835P</b>			
Cross Deck .....	7540291A		6641BR
Drive .....	7540461		6519BR
Eng. To Deck .....	7540364		6482BR
<b>14AI839H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540461		6519BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>14AI845H; 14AI849H; 14AJ84AH; 14AJ825H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
<b>14AJ825P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To Deck .....	7540364		6482BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540446		6605BR
<b>14AJ835P; 14AJ839P</b>			
Cross Deck .....	7540291A		6641BR
Drive .....	7540461		6519BR
Eng. To Deck .....	7540364		6482BR
<b>14AJ844H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
Eng. To V.S. ....	7540280		6447BR
<b>14AJ845H; 14AJ848H; 14AJ849H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
<b>14AJ849P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To Deck .....	7540364		6482BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540446		6605BR
<b>14AK825H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
Eng. To V.S. ....	7540280		6447BR
<b>14AP849P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To Deck .....	7540364		6482BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540446		6605BR
<b>14AQ825H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
Eng. To V.S. ....	7540280		6447BR
<b>14AR807P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To V.S. ....	7540467		6606BR
P.T.O.; W/Electric P.T.O. ....	7540475		6805BR
V.S. To Trans. ....	7540468		6556BR
<b>14AS82AH; 14AS83AH</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540461		6519BR
<b>14AS84AH; 14AS820H; 14AS825H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
Eng. To V.S. ....	7540280		6447BR
<b>14AS833H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540461		6519BR
<b>14AS840H</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540446		6605BR
<b>14AS843H; 14AS845H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
Eng. To V.S. ....	7540280		6447BR
<b>14AS848H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
<b>14AS849H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
Eng. To V.S. ....	7540280		6447BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>14AU804</b>			
Deck; W/46" Deck .....	7540474		6480BR
Deck; W/50" Deck .....	7540291A		6641BR
Drive .....	7540468		6556BR
P.T.O.; W/46" Deck .....	7540476		6416BR
P.T.O.; W/50" Deck .....	7540475		6805BR
Variable Speed .....	7540467		6606BR
<b>14AU804H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O. ....	7540476		6416BR
Variable Speed .....	7540467		6606BR
<b>14AU807P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To V.S. ....	7540467		6606BR
P.T.O. ....	7540475		6805BR
V.S. To Trans. ....	7540468		6556BR
<b>14AU844</b>			
Deck .....	7540349		6637BR
P.T.O. ....	7540350		6464BR
Trans. ....	7540446		6605BR
Variable Speed .....	7540280A		6447BR
<b>14AU844H; 14AU845H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
<b>14AV804P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To V.S. ....	7540467		6606BR
P.T.O. ....	7540475		6805BR
V.S. To Trans. ....	7540468		6556BR
<b>14AV807</b>			
Deck; W/46" Deck .....	7540474		6480BR
Deck; W/50" Deck .....	7540291A		6641BR
Drive .....	7540468		6556BR
P.T.O.; W/46" Deck .....	7540476		6416BR
P.T.O.; W/50" Deck .....	7540475		6805BR
Variable Speed .....	7540467		6606BR
<b>14AV807P</b>			
Drive .....	7540468		6556BR
P.T.O. ....	7540476		6416BR
Variable Speed .....	7540467		6606BR
<b>14AV808</b>			
Deck; W/46" Deck .....	7540474		6480BR
Deck; W/50" Deck .....	7540291A		6641BR
Drive .....	7540468		6556BR
P.T.O.; W/46" Deck .....	7540476		6416BR
P.T.O.; W/50" Deck .....	7540475		6805BR
Variable Speed .....	7540467		6606BR
<b>14AV808P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To V.S. ....	7540467		6606BR
P.T.O. ....	7540475		6805BR
V.S. To Trans. ....	7540468		6556BR
<b>14AV809H</b>			
Cross Deck .....	7540349		6637BR
P.T.O. ....	7540476		6416BR
<b>14AV809P</b>			
Drive .....	7540468		6556BR
Variable Speed .....	7540467		6606BR
<b>14AV818P</b>			
Cross Deck .....	7540291A		6641BR
Drive .....	7540349		6637BR
P.T.O.; W/Electric P.T.O. ....	7540475		6805BR
<b>14AV834P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To Deck .....	7540364		6482BR
P.T.O. ....	7540461		6519BR
<b>14AV844P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To Deck .....	7540364		6482BR
Eng. To V.S. ....	7540280		6447BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>14AV844P - Continued</b>			
V.S. To Trans. ....	7540446		6605BR
<b>14AW804H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540468		6556BR
P.T.O. ....	7540476		6416BR
Variable Speed .....	7540467		6606BR
<b>14AW804P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To V.S. ....	7540467		6606BR
P.T.O. ....	7540476		6416BR
V.S. To Trans. ....	7540468		6556BR
<b>14AW809H</b>			
Drive .....	7540468		6556BR
P.T.O. ....	7540476		6416BR
Variable Speed .....	7540467		6606BR
<b>14AW834H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540461		6519BR
<b>14AW844H</b>			
Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540280		6447BR
<b>14AY809</b>			
Deck; W/46" Deck .....	7540474		6480BR
Deck; W/50" Deck .....	7540291A		6641BR
Drive .....	7540468		6556BR
P.T.O.; W/46" Deck .....	7540476		6416BR
P.T.O.; W/50" Deck .....	7540475		6805BR
Variable Speed .....	7540467		6606BR
<b>14AY809P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To V.S. ....	7540467		6606BR
P.T.O. ....	7540475		6805BR
V.S. To Trans. ....	7540468		6556BR
<b>14AY833P; 14AY834P</b>			
Cross Deck .....	7540291A		6641BR
Drive .....	7540461		6519BR
Eng. To Deck .....	7540364		6482BR
<b>14AY844P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To Deck .....	7540364		6482BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540446		6605BR
<b>14AZ804P</b>			
Cross Deck .....	7540291A		6641BR
Drive .....	7540468		6556BR
P.T.O. ....	7540476		6416BR
Variable Speed .....	7540467		6606BR
<b>14AZ809</b>			
Deck; W/46" Deck .....	7540474		6480BR
Deck; W/50" Deck .....	7540291A		6641BR
Drive .....	7540468		6556BR
P.T.O.; W/46" Deck .....	7540476		6416BR
P.T.O.; W/50" Deck .....	7540475		6805BR
Variable Speed .....	7540467		6606BR
<b>14B9843H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR
<b>14BI839</b>			
Deck; W/46" Deck .....	7540349		6637BR
Deck; W/50" Deck .....	7540291A		6641BR
Eng. ....	7540461		6519BR
P.T.O.; W/46" Deck .....	7540350		6464BR
P.T.O.; W/50" Deck .....	7540364		6482BR
<b>14BS833H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540461		6519BR
<b>14BS843H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540446		6605BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>14BS845H</b>			
Cross Deck .....	7540349		6637BR
<b>14BV809</b>			
Deck; W/46" Deck .....	7540474		6480BR
Deck; W/50" Deck .....	7540291A		6641BR
Drive .....	7540468		6556BR
P.T.O.; W/46" Deck .....	7540476		6416BR
P.T.O.; W/50" Deck .....	7540475		6805BR
Variable Speed .....	7540467		6606BR
<b>14BV809H</b>			
Cross Deck .....	7540291A		6641BR
P.T.O. ....	7540476		6416BR
<b>14BY833</b>			
Deck; W/46" Deck .....	7540349		6637BR
Deck; W/50" Deck .....	7540291A		6641BR
Drive .....	7540461		6519BR
P.T.O.; W/46" Deck .....	7540350		6464BR
P.T.O.; W/50" Deck .....	7540364		6482BR
<b>14BY833P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To Deck .....	7540364		6482BR
P.T.O. ....	7540461		6519BR
<b>14BZ809H</b>			
Drive .....	7540468		6556BR
Variable Speed .....	7540467		6606BR
<b>21-4619; 21-4852</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>21-4853; 21-6209</b>			
Blade .....	7540118		6963
Gen. ....	7540134	7330	
Trans. ....	7540937	3590	6959
<b>21-6213</b>			
Blade .....	7540138	3500	6950
<b>21-6214</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>21-6215</b>			
Blade .....	7540118		6963
Gen. ....	7540134	7330	
Trans. ....	7540937	3590	6959
<b>21A6204</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>21A6205</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>21A6208</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>21A6209</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>21A6211</b>			
Blade .....	7540127		6966
Trans. ....	7540128		6935
<b>114-760</b>			
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>115-460</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>130-178A</b>			
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540154		6837

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>130-312D</b>			
Eng. To Deck .....	7540350		6464BR
<b>130-340; 130-360; 130-360A; 130-365</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>130-380A</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>130-390</b>			
Blade .....	7540107		6830
Trans. ....	7540111	2450	6845
<b>130-390A; 130-395A</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>130-400A</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>130-402; 130-402A</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>130-410</b>			
Blade .....	7540138	3500	6950
<b>130-415</b>			
Blade .....	7540147	3520	6952
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>130-420; 130-430</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>130-432; 130-433; 130-434; 130-435; 130-436; 130-437; 130-438; 130-439; 130-440; 130-441</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR
<b>130-442; 130-443; 130-444; 130-445; 130-446; 130-447; 130-448; 130-449; 130-450; 130-451</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR
<b>130-452; 130-453; 130-454; 130-455; 130-456; 130-457</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR
<b>130-460</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>130-465; 130-466</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>130-470; 130-475</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>130-480</b>			
Blade .....	7540145		6488BR
Trans.; W/31" Belt O.C. ....	7540136		6931
Trans.; W/52" Belt O.C. ....	7540147	3520	6952
<b>130-485A</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>130-490</b>			
Blade .....	7540145		6488BR
Trans.; W/31" Belt O.C. ....	7540136		6931
Trans.; W/52" Belt O.C. ....	7540147	3520	6952
<b>130-496A; 130-497; 130-497A; 130-498A</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>130-525A; 130-526; 130-526A</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>130-600</b>			
Eng. To Deck .....	7540371		6402BR
<b>130-640F; 130-642F; 130-643F</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR
<b>130-650F</b>			
Eng. To Deck .....	7540329		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>130-650G</b>			
Eng. To Deck .....	7540371		6402BR
<b>130-652F; 130-653F; 130-654F; 130-658F</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR
<b>130-658G</b>			
Eng. To Deck; W/69 3/4" Belt O.C. ....	7540329		6630BR
Eng. To Deck; W/74 3/4" Belt O.C. ....	7540371		6402BR
<b>130-659F</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR
<b>130-659G</b>			
Eng. To Deck; W/69 3/4" Belt O.C. ....	7540329		6630BR
Eng. To Deck; W/74 3/4" Belt O.C. ....	7540371		6402BR
<b>130-670G</b>			
Eng. To Deck .....	7540371		6402BR
<b>130-673G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>130-678G; 130-679G; 130-684G; 130-689G</b>			
Eng. To Deck .....	7540371		6402BR
<b>130-704</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR
<b>130-720A</b>			
Belt .....	7540250		6853
Drive .....	7540255		6839
Traction .....	7540248		6431BR
Trans. ....	7540245		6859
<b>130-720H</b>			
Eng. To Deck .....	7540350		6464BR
<b>130-734G</b>			
Eng. To Deck .....	7540371		6402BR
<b>130-760</b>			
Blade; W/53" Belt O.C. ....	7540250	2530	6853
Blade; W/56" Belt O.C. ....	7540230		6755BR
J.S. ....	7540245		6859
Trans. ....	7540255		6837
<b>130-760A</b>			
Belt .....	7540250		6853
Drive .....	7540255		6839
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540154		6837
Traction .....	7540248		6431BR
Trans. ....	7540245		6859
<b>130-780</b>			
Drive .....	7540245		6859
<b>130-780A</b>			
Deck .....	7540246		6354
Drive .....	7540154		6837
J.S. ....	7540245		6859
<b>130-781A</b>			
Deck .....	7540230		6755BR
<b>130-784G</b>			
Eng. To Deck .....	7540371		6402BR
<b>130-793; 130-795; 130-796</b>			
Blade .....	7540264		6639BR
<b>130-796A</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>130-800; 130-800H; 130-801; 130-802</b>			
Cross Deck .....	7540349		6637BR
Transaxle .....	7540248		6431BR
<b>130-802H</b>			
Transaxle .....	7540248		6431BR
<b>130-803; 130-803H; 130-804</b>			
Cross Deck .....	7540349		6637BR
Transaxle .....	7540248		6431BR
<b>130-805</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck; W/38" Deck .....	7540329		6630BR
Transaxle .....	7540248		6431BR
<b>130-806; 130-807; 130-808; 130-808H; 130-809; 130-809H</b>			
Cross Deck .....	7540349		6637BR
Transaxle .....	7540248		6431BR
<b>130-824H</b>			
Cross Deck .....	7540349		6637BR
<b>131-132</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR
<b>131-340; 131-360; 131-365</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>131-380A</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>131-390</b>			
Blade .....	7540107		6830
Trans. ....	7540111	2450	6845
<b>131-390A</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>131-402A</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>131-410</b>			
Blade .....	7540138	3500	6950
<b>131-410A</b>			
Blade .....	7540251		6809BR
Eng. To Vari-Speed .....	7540187	3240	6924
Vari-Speed To Trans. ....	7540136		6931
<b>131-412</b>			
Blade .....	7540138	3500	6950
<b>131-412A</b>			
Blade .....	7540251		6809BR
Eng. To Vari-Speed .....	7540187	3240	6924
Vari-Speed To Trans. ....	7540136		6931
<b>131-415; 131-418</b>			
Blade .....	7540147	3520	6952
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>131-420; 131-425; 131-430</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>131-432F; 131-433; 131-434</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR
<b>131-435</b>			
Blade .....	7540127		6966
Eng. To Deck .....	7540329		6630BR
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>131-436; 131-437; 131-438; 131-439; 131-440; 131-441; 131-442; 131-443; 131-444; 131-445</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
131-446; 131-447; 131-448; 131-449; 131-450; 131-451; 131-452; 131-452F; 131-453; 131-454 Eng. To Deck; W/38" Deck .....	7540329		6630BR
131-455; 131-456; 131-457 Eng. To Deck; W/38" Deck .....	7540329		6630BR
131-460; 131-465; 131-470; 131-475 Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
131-480; 131-485 Blade .....	7540145		6488BR
Eng. ....	7540147	3520	6952
Trans.; W/31" Belt O.C. ....	7540136		6931
Trans.; W/52" Belt O.C. ....	7540147	3520	6952
131-485A Blade .....	7540151		6967
Trans. ....	7540191		6865
131-490; 131-495 Blade .....	7540145		6488BR
Eng. ....	7540147	3520	6952
Trans.; W/31" Belt O.C. ....	7540136		6931
Trans.; W/52" Belt O.C. ....	7540147	3520	6952
131-497A; 131-498A Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
131-526A Blade .....	7540195		6854
Trans. ....	7540198		6451BR
131-640F; 131-650F; 131-652F; 131-658F; 131-659F; 131-660F; 131-663F; 131-704F Eng. To Deck; W/38" Deck .....	7540329A		6630BR
131-730A Blade .....	7540250		6853
Intermediate Drive .....	7540251		6809BR
Trans. ....	7540248		6431BR
131-754F Eng. To Deck; W/38" Deck .....	7540329A		6630BR
131-763A J.S. ....	7540245		6859
Transaxle .....	7540154		6837
131-764A Blade .....	7540230		6755BR
J.S. ....	7540245		6859
Transaxle .....	7540154		6837
131-796A Blade .....	7540244		6840
Trans. ....	7540207		6842
131-800 Eng. To V.S. ....	7540358		6419BR
131-800H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
131-801 Eng. To V.S. ....	7540358		6419BR
131-801H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
131-804 Eng. To V.S. ....	7540358		6419BR
131-804H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
131-805 Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540358		6419BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
131-805H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
131-806 Eng. To V.S. ....	7540358		6419BR
131-806H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
131-807 Eng. To V.S. ....	7540358		6419BR
131-807H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
131-808 Eng. To V.S. ....	7540358		6419BR
131-808H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
131-809 Eng. To V.S. ....	7540358		6419BR
131-809H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
131-824H Cross Deck .....	7540349		6637BR
132-050 Deck .....	7540246		6354
Trans. ....	7540248		6431BR
132-312D Deck .....	7540151		6967
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
132-322D V.S. To Trans. ....	7540281		6405BR
132-332D Deck .....	7540151		6967
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
132-360; 132-360A; 132-365 Blade .....	7540107		6830
Trans. ....	7540936		6847
132-380; 132-385 Blade; W/25" Deck .....	7540138	3500	6950
Blade; W/30" Deck .....	7540167		6964
Trans.; W/25" Deck .....	7540164	2630	6863
Trans.; W/30" Deck .....	7540198		6451BR
132-390 Blade .....	7540198		6451BR
Trans. ....	7540164	2630	6863
132-395 Blade .....	7540167		6964
Trans. ....	7540164	2630	6863
132-395A Blade .....	7540167		6964
Trans. ....	7540198		6451BR
132-400A Blade .....	7540101		6517BR
Trans. ....	7540188	3510	
132-402; 132-402A Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
132-410; 132-412 Blade .....	7540138	3500	6950
132-412A Blade; W/24" Belt O.C. ....	7540187	3240	

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>132-412A - Continued</b>			
Blade; W/31" Belt O.C. ....	7540136	3310	
Trans. ....	7540251		6809BR
<b>132-415; 132-418</b>			
Blade ....	7540147	3520	6952
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>132-425</b>			
Blade ....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>132-431E</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
V.S. To Trans. ....	7540281		6405BR
<b>132-435</b>			
Blade ....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>132-440F</b>			
V.S. To Trans. ....	7540281		6405BR
<b>132-440R</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>132-441F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
V.S. To Trans. ....	7540281		6405BR
<b>132-450F; 132-451F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>132-452F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
V.S. To Trans. ....	7540281		6405BR
<b>132-460</b>			
Blade .....	7540166	3620	6962
Trans. ....	7540118		6963
<b>132-465; 132-465A</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>132-470</b>			
Blade .....	7540166	3620	6962
Trans. ....	7540118		6963
<b>132-475</b>			
Blade .....	7540127		6966
Trans. ....	7540166		6962
<b>132-480; 132-485</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>132-490; 132-495</b>			
Blade .....	7540145		6488BR
Trans.; W/31" Belt O.C. ....	7540136		6931
Trans.; W/50" Belt O.C. ....	7540138	3500	6950
<b>132-497; 132-497A; 132-498; 132-498A</b>			
Blade .....	7540145		6488BR
Trans.; W/62" Belt O.C. ....	7540228		6962
Trans.; W/82" Belt O.C. ....	7540226		6551BR
<b>132-510</b>			
Deck; W/Rear Discharge .....	7540264		6639BR
Eng. ....	7540241		6494BR
Trans. ....	7540240		6511BR
<b>132-510B</b>			
Deck; W/Side Discharge .....	7540264		6639BR
Eng. ....	7540241		6494BR
Trans. ....	7540240		6511BR
<b>132-511</b>			
Deck .....	7540264		6639BR
Eng. ....	7540241		6494BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>132-511 - Continued</b>			
Trans. ....	7540240		6511BR
<b>132-520</b>			
Deck; W/Rear Discharge .....	7540264		6639BR
Eng. ....	7540241		6494BR
Trans. ....	7540240		6511BR
<b>132-520B</b>			
Deck; W/Side Discharge .....	7540264		6639BR
Eng. ....	7540241		6494BR
Trans. ....	7540240		6511BR
<b>132-521</b>			
Deck .....	7540264		6639BR
Eng. ....	7540241		6494BR
Trans. ....	7540240		6511BR
<b>132-525; 132-525A</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>132-530</b>			
Deck; W/Rear Discharge .....	7540264		6639BR
Eng. ....	7540241		6494BR
Trans. ....	7540240		6511BR
<b>132-531</b>			
Deck .....	7540264		6639BR
Eng. ....	7540241		6494BR
Trans. ....	7540240		6511BR
<b>132-550</b>			
Deck; W/Rear Discharge .....	7540264		6639BR
Eng. ....	7540241		6494BR
Trans. ....	7540240		6511BR
<b>132-551</b>			
Deck .....	7540264		6639BR
Eng. ....	7540241		6494BR
Trans. ....	7540240		6511BR
<b>132-620</b>			
Blade; W/67" Belt O.C. ....	7540151		6967
Blade; W/69" Belt O.C. ....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>132-621</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>132-640F; 132-642F; 132-650F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-650G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-651F</b>			
Eng. To Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-651G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-652F; 132-657F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-657G; 132-659G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-660F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>132-660G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-661F; 132-661G</b>			
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-662F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-663G; 132-666G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-667F</b>			
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-667G; 132-668G; 132-669G; 132-670G;</b>			
<b>132-673G; 132-677G; 132-678G; 132-679G;</b>			
<b>132-689G; 132-690G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>132-698</b>			
Blade; W/67" Belt O.C. ....	7540151		6967
Blade; W/69" Belt O.C. ....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>132-700; 132-719</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Trans. ....	7540372		6881
<b>132-720G; 132-726G; 132-729G</b>			
Deck .....	7540371A		6402BR
Drive .....	7540372		6881
<b>132-730; 132-739; 132-740</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Drive .....	7540372		6881
<b>132-740G</b>			
Deck .....	7540371A		6402BR
Drive .....	7540372		6881
<b>132-750; 132-760</b>			
Deck; W/38" Deck .....	7540329A		6630BR
Deck; W/42" Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>132-760G</b>			
Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>132-764; 132-784</b>			
Blade; W/56" Belt O.C. ....	7540230		6755BR
Blade; W/59" Belt O.C. ....	7540245		6859
Deck .....	7540246		6354
Drive .....	7540244		6840
<b>132-790G</b>			
Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>132-796</b>			
Blade; W/30" Belt O.C. ....	7540196		6830
Blade; W/62" Belt O.C. ....	7540198		6451BR
Trans. ....	7540207		6842
<b>132-800H</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>132-808H</b>			
Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>132-809H</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>132-820H</b>			
Cross Deck .....	7540349		6637BR
<b>132A670G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133-360; 133-362</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>133-380; 133-385; 133-390; 133-395</b>			
Blade; W/25" Deck .....	7540138	3500	6950
Blade; W/30" Deck .....	7540167		6964
Trans.; W/25" Deck .....	7540164	2630	6863
Trans.; W/30" Deck .....	7540198		6451BR
<b>133-404; 133-410</b>			
Blade .....	7540138	3500	6950
<b>133-420</b>			
Blade .....	7540147	3520	6952
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>133-430; 133-434; 133-435</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>133-440; 133-445</b>			
Blade .....	7540178	3820	6982
Trans.; W/48" Belt O.C. ....	7540200		6848
Trans.; W/50" Belt O.C. ....	7540179		6950
<b>133-460</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>133-465</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540136		6931
<b>133-470</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>133-495</b>			
Blade .....	7540145		6488BR
Trans. ....	7540127		6966
<b>133-500</b>			
Blade .....	7540249		6930
Trans. ....	7540264		6639BR
<b>133-501</b>			
Blade .....	7540241		6494BR
Deck .....	7540264		6639BR
Trans. ....	7540240		6511BR
<b>133-506</b>			
Eng. ....	7540241		6494BR
<b>133-526</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>133-585</b>			
Variator; W/29" Belt O.C. ....	7540183	3290	6929
Variator; W/31" Belt O.C. ....	7540136		6931
<b>133-630</b>			
Blade .....	7540151		6967
Trans. ....	7540266		6775BR

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>133-638</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>133-699</b>			
Belt; W/39" Belt O.C. ....	7540271		6557BR
Belt; W/85" Belt O.C. ....	7540266		6775BR
<b>133-760</b>			
Blade; W/51" Belt O.C. ....	7540251		6809BR
Blade; W/53" Belt O.C. ....	7540250		6853
Blade; W/59" Belt O.C. ....	7540245		6859
Trans. ....	7540255		6837
<b>133-784</b>			
Blade; W/56" Belt O.C. ....	7540230		6755BR
Blade; W/59" Belt O.C. ....	7540245		6859
Deck .....	7540246		6354
Drive .....	7540243		6846
Trans. ....	7540255	2370	6837
<b>133B450E</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
V.S. To Trans. ....	7540281		6405BR
<b>133B451E</b>			
Deck; W/36" Deck .....	7540364		6482BR
Deck; W/38" Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>133B560B</b>			
Deck .....	7540264		6639BR
Eng. ....	754-0241A		6494BR
Trans. ....	7540240		6511BR
<b>133C450E; 133D451E</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
V.S. To Trans. ....	7540281		6405BR
<b>133E450F; 133E452F</b>			
Deck; W/36" Deck .....	7540364		6482BR
Deck; W/38" Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>133E660F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133E661F; 133E667F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>133G699G</b>			
Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>133H451F; 133H470F; 133H471F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
V.S. To Trans. ....	7540281		6405BR
<b>133H660F; 133H661F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>133H671F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133I450F; 133I470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
V.S. To Trans. ....	7540281		6405BR
<b>133I600F</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540329A		6630BR
<b>133I660F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133I670F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>133I670G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133I671F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>133I677F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133K600F</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>133K619G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133K673G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133K677F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>133K677G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133K679G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133K694G; 133K697G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>133L660F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>133L660G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133L661G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133L662F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133L670F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>133L670G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133L671F; 133L677F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>133L679G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133L690G</b>			
Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>133M603G; 133M609G</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540371A		6402BR
<b>133M617G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133M619G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133M660G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>133M670G; 133M679G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133M690G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>133N660G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133N699G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>133O660G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133O660H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>133O673G; 133P660G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133P660H</b>			
Cross Deck .....	7540440		6477BR
Eng. ....	7540280		6447BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540370		6439BR
<b>133P670G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133P670H; 133P678H; 133P679H</b>			
Cross Deck .....	7540440		6477BR
Eng. ....	7540280		6447BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540370		6439BR
<b>133P699G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>133Q668H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>133Q677G</b>			
Eng. To Deck; W/69 3/4" Belt O.C. ....	7540329A		6630BR
Eng. To Deck; W/74 3/4" Belt O.C. ....	7540371A		6402BR
<b>133Q677GF</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>133Q678H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>133Q694G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>133X679G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133Y679H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>133Z619G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>133Z699G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>134-093</b>			
Eng. To Deck .....	7540342		6866
<b>134-330; 134-334</b>			
Trans. ....	7540239	2290	6829

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>134-340; 134-341; 134-344; 134-360</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>134-360A; 134-362A</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>134-364</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>134-380</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540108	2460	6846
<b>134-380A; 134-385A</b>			
Blade; W/25" Deck .....	7540138	3500	6950
Blade; W/30" Deck .....	7540167		6964
Trans.; W/25" Deck .....	7540164	2630	6863
Trans.; W/30" Deck .....	7540198		6451BR
<b>134-390A</b>			
Blade .....	7540167		6964
Trans. ....	7540164	2630	6863
<b>134-395</b>			
Blade; W/30" Blade .....	7540167		6964
Blade; W/36" Blade .....	7540279		6965
Deck .....	7540198		6451BR
<b>134-395A</b>			
Blade .....	7540167		6964
Trans. ....	7540164	2630	6863
<b>134-397; 134-398</b>			
Blade; W/30" Blade .....	7540167		6964
Blade; W/36" Blade .....	7540279		6965
Deck .....	7540198		6451BR
<b>134-400A</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>134-402A; 134-405; 134-405A; 134-406;</b>			
<b>134-406A; 134-407; 134-407A</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>134-410; 134-410A</b>			
Blade .....	7540138	3500	6950
<b>134-420; 134-420A</b>			
Blade .....	7540147	3520	6952
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>134-430; 134-430A; 134-434; 134-434A;</b>			
<b>134-435; 134-435A</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>134-440; 134-440A; 134-445; 134-445A;</b>			
<b>134-450</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540185		6849
<b>134-460A; 134-465A</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>134-470; 134-475; 134-480; 134-485</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>134-490; 134-495; 134-495A; 134-497;</b>			
<b>134-497A</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>134-500; 134-501</b>			
Blade .....	7540249		6930

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>134-500; 134-501 - Continued</b>			
Trans. ....	7540264		6639BR
<b>134-502; 134-504; 134-506</b>			
Blade .....	7540241	6494BR	
Deck .....	7540264	6639BR	
Trans. ....	7540240	6511BR	
<b>134-510</b>			
Blade .....	7540249	6930	
Trans. ....	7540264	6639BR	
<b>134-511</b>			
Blade .....	7540249	6930	
<b>134-512</b>			
Blade .....	7540249	6930	
Trans. ....	7540264	6639BR	
<b>134-514; 134-516; 134-518</b>			
Eng. To Variator .....	7540241	6494BR	
Variator To Trans. ....	7540240	6511BR	
<b>134-526; 134-528; 134-529</b>			
Blade .....	7540195	6854	
Trans. ....	7540198	6451BR	
<b>134-585A</b>			
Eng. To Variator .....	7540157	6928	
Variator To Trans. ....	7540136	6931	
<b>134-618; 134-619</b>			
Belt; W/39" Belt O.C. ....	7540271	6557BR	
Belt; W/85" Belt O.C. ....	7540266	6775BR	
<b>134-620</b>			
Drive .....	7540276	6848	
<b>134-631</b>			
Drive .....	7540151	6967	
<b>134-638; 134-668</b>			
Blade .....	7540145	6488BR	
Trans. ....	7540266	6775BR	
<b>134-669</b>			
Belt; W/39" Belt O.C. ....	7540271	6557BR	
Belt; W/85" Belt O.C. ....	7540266	6775BR	
<b>134-698</b>			
Blade .....	7540145	6488BR	
Trans. ....	7540266	6775BR	
<b>134-699</b>			
Belt; W/39" Belt O.C. ....	7540271	6557BR	
Belt; W/85" Belt O.C. ....	7540266	6775BR	
<b>134-720; 134-721; 134-722; 134-723; 134-724;</b>			
<b>134-725; 134-726; 134-727; 134-730; 134-731</b>			
Trans. ....	7540248	6431BR	
<b>134-732; 134-733; 134-734; 134-735; 134-736;</b>			
<b>134-737</b>			
Trans. ....	7540248	6431BR	
<b>134-760; 134-764; 134-765</b>			
Eng. To J.S. ....	7540255	6837	
J.S. To Trans. ....	7540245	6859	
<b>134-784</b>			
Blade .....	7540230	6755BR	
Trans. ....	7540246	6354	
<b>134-785; 134-786; 134-794; 134-795; 134-796</b>			
Eng. To J.S. ....	7540255	6837	
J.S. To Trans. ....	7540245	6859	
<b>134B451E</b>			
Eng. To V.S. ....	7540280	6447BR	
V.S. To Trans. ....	7540281	6405BR	
<b>134B560B; 134B561B</b>			
Deck .....	7540264	6639BR	
Eng. ....	754-0241A	6494BR	
Trans. ....	7540240	6511BR	
<b>134C450E</b>			
Deck .....	7540364	6482BR	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>134C450E - Continued</b>			
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>134C451E</b>			
V.S. To Trans. ....	7540281		6405BR
<b>134D694G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>134E470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>134E660F</b>			
Eng. ....	7540280		6447BR
Trans. ....	7540280		6447BR
<b>134E661F</b>			
Deck .....	7540433		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>134E667F</b>			
Eng. ....	7540370		6439BR
Trans. ....	7540280		6447BR
<b>134G660G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540370		6439BR
Trans. ....	7540280		6447BR
<b>134G670G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>134G690G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>134H450F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>134H451E</b>			
Deck .....	7540364		6482BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>134H451F; 134H470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>134H607F</b>			
Cross Deck .....	7540349		6637BR
<b>134H660F</b>			
Deck .....	7540433		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>134H667F; 134H670F</b>			
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>134I450F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>134I600F</b>			
Cross Deck .....	7540349		6637BR
Deck .....	7540433		6630BR
<b>134I660F; 134I665F; 134I677F</b>			
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>134K675G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>134K677F</b>			
Deck .....	7540433		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>134K678F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134K679G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134L471F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>134L660F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134L660G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134L661F; 134L667F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134L667G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134L670F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134L670G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134L671F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134L673G; 134L675G; 134L679G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134M605G</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540371A		6402BR
<b>134M660G; 134M670G; 134M673G; 134M675G;</b>			
<b>134M678G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134M678H</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>134M679G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134M690G; 134M695G</b>			
Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>134M699G</b>			
Eng. To Deck .....	7540371A		6402BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>134M699G - Continued</b>			
Trans. ....	7540441		6417BR
<b>134N604H</b>			
Cross Deck .....	7540349		6637BR
<b>134O670G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134O675G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>134O678G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134O690G; 134O695G</b>			
Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>134O695H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>134O699G</b>			
Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>134O699H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>134P660G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134P668H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134P670G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134P670H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134P678G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134P679H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134P698H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>134Q677G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134Q694G; 134Q699G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>134Q699H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>134R617G; 134R619G; 134R678G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>134R695G; 134R699G; 134X694G; 134X699G</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>134Y450F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>134Y451E</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>134Y451F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>134Y452</b>			
Deck .....	7540364		6482BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>134Y452F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>134Y470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>134Y472</b>			
Deck .....	7540364		6482BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>134Y472F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>135-280</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>135-330; 135-334</b>			
Trans. ....	7540239	2290	6829
<b>135-340</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>135-360</b>			
Blade .....	7540107		6830
Trans.; W/31" Belt O.C. ....	7540935	2310	6831
Trans.; W/47" Belt O.C. ....	7540936		6847
<b>135-360A; 135-362A</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>135-364</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>135-380</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540108	2460	6846
<b>135-380A</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>135-385</b>			
Blade; W/25" Deck .....	7540138	3500	6950

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>135-385 - Continued</b>			
Blade; W/30" Deck .....	7540167		6964
Trans.; W/25" Deck .....	7540164	2630	6863
Trans.; W/30" Deck .....	7540198		6451BR
<b>135-385A</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>135-390</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>135-390A; 135-395; 135-395A</b>			
Blade; W/30" Blade .....	7540167		6964
Blade; W/36" Blade .....	7540279		6965
Deck .....	7540198		6451BR
Trans. ....	7540198		6451BR
<b>135-397; 135-398</b>			
Blade; W/30" Blade .....	7540167		6964
Blade; W/36" Blade .....	7540279		6965
Deck .....	7540198		6451BR
<b>135-400; 135-400A</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>135-402; 135-402A; 135-406; 135-406A</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>135-410; 135-410A</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>135-420A; 135-425A</b>			
Blade .....	7540147	3520	6952
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>135-430; 135-430A; 135-435; 135-435A</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>135-440A; 135-445; 135-445A</b>			
Blade .....	7540178	3820	6982
Trans.; W/48" Belt O.C. ....	7540200		6848
Trans.; W/50" Belt O.C. ....	7540179		6950
<b>135-460; 135-460A</b>			
Blade .....	7540151		6967
Trans.; W/31" Belt O.C. ....	7540136		6931
Trans.; W/50" Belt O.C. ....	7540138	3500	6950
<b>135-465</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>135-465A</b>			
Blade; W/66" Belt O.C. ....	7540127		6966
Blade; W/67" Belt O.C. ....	7540151		6967
Trans.; W/31" Belt O.C. ....	7540136		6931
Trans.; W/50" Belt O.C. ....	7540138	3500	6950
Trans.; W/62" Belt O.C. ....	7540166	3620	6962
<b>135-470A; 135-475A</b>			
Blade .....	7540151		6967
Trans.; W/65" Belt O.C. ....	7540191		6865
Trans.; W/66" Belt O.C. ....	7540127		6966
<b>135-476</b>			
Blade .....	7540145		6488BR
Trans.; W/37" Belt O.C. ....	7540173		6937
Trans.; W/65" Belt O.C. ....	7540191		6865
<b>135-477</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>135-480; 135-480A</b>			
Blade .....	7540151		6967
Trans.; W/65" Belt O.C. ....	7540191		6865





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>135-480; 135-480A - Continued</b>			
Trans.; W/66" Belt O.C. ....	7540127		6966
<b>135-485</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>135-485A</b>			
Blade .....	7540151		6967
Trans.; W/65" Belt O.C. ....	7540191		6865
Trans.; W/66" Belt O.C. ....	7540127		6966
<b>135-495; 135-495A; 135-496; 135-497; 135-497A</b>			
Blade .....	7540145		6488BR
Trans.; W/37" Belt O.C. ....	7540173		6937
Trans.; W/65" Belt O.C. ....	7540191		6865
<b>135-500</b>			
Trans. ....	7540249		6930
<b>135-501</b>			
Blade .....	7540264		6639BR
<b>135-502</b>			
Eng. To Variator .....	7540241		6494BR
Variator To Trans. ....	7540240		6511BR
<b>135-504; 135-506</b>			
Blade .....	7540241		6494BR
Deck .....	7540264		6639BR
Trans. ....	7540240		6511BR
<b>135-510; 135-511</b>			
Blade .....	7540249		6930
Trans. ....	7540264		6639BR
<b>135-512; 135-514; 135-516; 135-518</b>			
Eng. To Variator .....	7540241		6494BR
Variator To Trans. ....	7540240		6511BR
<b>135-520A; 135-525A; 135-526; 135-528; 135-529</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>135-600</b>			
Blade; W/42" Deck .....	7540371A		6402BR
Cross Deck; W/46" Deck .....	7540440		6477BR
Deck .....	7540329A		6630BR
Eng. To Deck; W/46" Deck .....	7540439		6406BR
<b>135-618</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>135-619</b>			
Belt; W/39" Belt O.C. ....	7540271		6557BR
<b>135-620</b>			
Drive .....	7540276		6848
<b>135-628; 135-637</b>			
V.S. To Trans. ....	7540281		6405BR
<b>135-638</b>			
Eng. To Variator .....	7540280		6447BR
Variator To Trans. ....	7540281		6405BR
<b>135-666</b>			
Belt; W/39" Belt O.C. ....	7540271		6557BR
<b>135-668P</b>			
V.S. To Trans. ....	7540281		6405BR
<b>135-669</b>			
Blade - Right .....	7540271		6557BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>135-687</b>			
V.S. To Trans. ....	7540281		6405BR
<b>135-692</b>			
Belt; W/39" Belt O.C. ....	7540271		6557BR
Transaxle .....	7540266		6775BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>135-696B</b>			
Deck .....	7540145A		6488BR
Drive .....	7540266		6775BR
<b>135-698</b>			
Transaxle .....	7540266		6775BR
V.S. To Trans. ....	7540281		6405BR
<b>135-699</b>			
Belt; W/39" Belt O.C. ....	7540271		6557BR
<b>135-704; 135-705; 135-714; 135-715</b>			
Belt .....	7540293		6501BR
Trans. ....	7540229		6852
<b>135-716</b>			
Blade - Right .....	7540271		6557BR
<b>135-720; 135-721; 135-722; 135-723; 135-724; 135-725; 135-726; 135-727</b>			
Trans. ....	7540248		6431BR
<b>135-728; 135-729</b>			
Transaxle .....	7540248		6431BR
<b>135-730; 135-731; 135-732; 135-733; 135-734; 135-735; 135-736; 135-737</b>			
Trans. ....	7540248		6431BR
<b>135B560B</b>			
Blade .....	7540264		6639BR
Eng. ....	754-0241A		6494BR
Trans. ....	7540240		6511BR
<b>135C450F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>135C451E</b>			
Blade .....	7540364		6482BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>135C451F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>135C452E</b>			
Blade .....	7540364		6482BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>135C470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>135C472E</b>			
Blade .....	7540364		6482BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>135D614G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>135E450F</b>			
Blade .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>135E470E</b>			
Eng. To V.S. ....	7540280		6447BR
<b>135E470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>135E660F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>135G660G; 135G665G; 135G670G; 135G675G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135G679H</b>			
Cross Deck .....	7540440		<b>6477BR</b>
Eng. To Deck .....	7540439		<b>6406BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135G695G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
<b>135H450E; 135H450F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540281		<b>6405BR</b>
<b>135H451E</b>			
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540281		<b>6405BR</b>
<b>135H470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540281		<b>6405BR</b>
<b>135H660F; 135H670F</b>			
Eng. To Deck .....	7540433		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135HL470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		<b>6630BR</b>
<b>135L470F</b>			
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540281		<b>6405BR</b>
<b>135L471F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540281		<b>6405BR</b>
<b>135L660F</b>			
Eng. To Deck .....	7540433		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135L660G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135L661F; 135L667F</b>			
Eng. To Deck .....	7540433		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135L667G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135L670F</b>			
Eng. To Deck .....	7540433		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135L670G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135L671F</b>			
Eng. To Deck .....	7540433		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135L673G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>135L675F</b>			
Eng. To Deck .....	7540433		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135L675G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135L677F</b>			
Eng. To Deck .....	7540433		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135M660G; 135M670G; 135M673G; 135M675G; 135M678G; 135M679G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135M699G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Trans. ....	7540441		<b>6417BR</b>
<b>135N470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540281		<b>6405BR</b>
<b>135N604F</b>			
Cross Deck .....	7540349		<b>6637BR</b>
<b>135N694H</b>			
Trans. ....	7540441		<b>6417BR</b>
<b>135O660G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135O673H</b>			
Cross Deck .....	7540440		<b>6477BR</b>
Eng. To Deck .....	7540439		<b>6406BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135O675G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135O675H</b>			
Cross Deck .....	7540440		<b>6477BR</b>
Eng. To Deck .....	7540439		<b>6406BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
<b>135O678G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135O679H</b>			
Cross Deck .....	7540440		<b>6477BR</b>
Eng. To Deck .....	7540439		<b>6406BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>135O695G</b>			
Blade .....	7540371A		<b>6402BR</b>
Drive .....	7540441		<b>6417BR</b>
<b>135O695H</b>			
Cross Deck .....	7540440		<b>6477BR</b>
Eng. To Deck .....	7540439		<b>6406BR</b>
Trans. ....	7540441		<b>6417BR</b>
<b>135O697G; 135O698G</b>			
Blade .....	7540371A		<b>6402BR</b>
Drive .....	7540441		<b>6417BR</b>
<b>135O765N</b>			
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>				<b>MTD PRODUCTS, INC. - Continued</b>			
<b>135P668G</b>				<b>136-362A</b>			
Blade .....	7540440		6477BR	Blade .....	7540107		6830
Eng. ....	7540280		6447BR	Trans. ....	7540936		6847
P.T.O. ....	7540439		6406BR				
Trans. ....	7540370		6439BR	<b>136-364</b>			
				Blade .....	7540935	2310	6831
<b>135P668H</b>				Trans. ....	7540936	2470	6847
Cross Deck .....	7540440		6477BR				
Eng. To Deck .....	7540439		6406BR	<b>136-370</b>			
Eng. To V.S. ....	7540280		6447BR	Blade .....	7540935	2310	6831
V.S. To Trans. ....	7540370		6439BR	Trans. ....	7540108	2460	6846
<b>135P670G</b>				<b>136-380</b>			
Eng. To Deck .....	7540371A		6402BR	Blade .....	7540935	2310	6831
Eng. To V.S. ....	7540280		6447BR	Trans. ....	7540111	2450	6845
V.S. To Trans. ....	7540370		6439BR				
				<b>136-380A; 136-385A</b>			
<b>135P670H</b>				Blade .....	7540138	3500	6950
Cross Deck .....	7540440		6477BR	Trans. ....	7540198		6451BR
Eng. To Deck .....	7540439		6406BR				
Eng. To V.S. ....	7540280		6447BR	<b>136-390</b>			
V.S. To Trans. ....	7540370		6439BR	Blade .....	7540935	2310	6831
				Trans. ....	7540111	2450	6845
<b>135P678G</b>							
Eng. To Deck .....	7540371A		6402BR	<b>136-390A; 136-395; 136-395A; 136-397;</b>			
Eng. To V.S. ....	7540280		6447BR	<b>136-398</b>			
V.S. To Trans. ....	7540370		6439BR	Blade .....	7540167		6964
				Trans. ....	7540198		6451BR
<b>135P679H</b>							
Cross Deck .....	7540440		6477BR	<b>136-400; 136-400A</b>			
Eng. To Deck .....	7540439		6406BR	Blade .....	7540188		6951
Eng. To V.S. ....	7540280		6447BR	Trans. ....	7540101		6517BR
V.S. To Trans. ....	7540370		6439BR				
				<b>136-402; 136-402A; 136-406; 136-406A</b>			
<b>135Q660G</b>				Blade .....	7540188		6951
Eng. To Deck .....	7540371A		6402BR	Drive; W/24" Belt O.C. ....	7540187	3240	6924
Eng. To V.S. ....	7540280		6447BR	Drive; W/31" Belt O.C. ....	7540136		6931
V.S. To Trans. ....	7540370		6439BR				
				<b>136-410</b>			
<b>135Q695G; 135Q699G</b>				Blade .....	7540138	3500	6950
Eng. To Deck .....	7540371A		6402BR	Trans. ....	7540101		6517BR
Trans. ....	7540441		6417BR				
				<b>136-410A</b>			
<b>135Q699H</b>				Blade .....	7540138	3500	6950
Cross Deck .....	7540440		6477BR				
Eng. To Deck .....	7540439		6406BR	<b>136-420</b>			
Trans. ....	7540441		6417BR	Blade .....	7540147	3520	6952
				Trans. ....	7540135		6925
<b>135R619G</b>							
Eng. To Deck .....	7540371A		6402BR	<b>136-420A</b>			
Eng. To V.S. ....	7540280		6447BR	Blade .....	7540147	3520	6952
V.S. To Trans. ....	7540370		6439BR	Trans.; W/25" Belt O.C. ....	7540135		6925
				Trans.; W/31" Belt O.C. ....	7540136		6931
<b>135R699G</b>							
Blade .....	7540371A		6402BR	<b>136-430; 136-430A; 136-435A</b>			
Drive .....	7540441		6417BR	Blade .....	7540127		6966
				Trans.; W/25" Belt O.C. ....	7540135		6925
<b>135S613G</b>				Trans.; W/31" Belt O.C. ....	7540136		6931
Eng. To Deck .....	7540371A		6402BR				
Eng. To V.S. ....	7540280		6447BR	<b>136-445; 136-445A</b>			
V.S. To Trans. ....	7540370		6439BR	Blade .....	7540178	3820	6982
				Trans.; W/48" Belt O.C. ....	7540200		6848
<b>135S693H; 135V694H</b>				Trans.; W/50" Belt O.C. ....	7540179		6950
Cross Deck .....	7540440		6477BR				
Eng. To Deck .....	7540439		6406BR	<b>136-460A; 136-465A</b>			
Trans. ....	7540441		6417BR	Blade .....	7540151		6967
				Drive; W/31" Belt O.C. ....	7540136		6931
<b>135X694G</b>				Drive; W/50" Belt O.C. ....	7540138	3500	6950
Eng. To Deck .....	7540371A		6402BR				
Trans. ....	7540441		6417BR	<b>136-475; 136-475A; 136-480; 136-480A;</b>			
				<b>136-485A</b>			
<b>136-330; 136-334</b>				Blade .....	7540151		6967
Blade .....	7540107		6830	Trans. ....	7540191		6865
<b>136-340; 136-360</b>				<b>136-495; 136-495A; 136-497; 136-497A</b>			
Blade .....	7540935	2310	6831	Blade .....	7540145		6488BR
Trans. ....	7540936	2470	6847	Drive; W/37" Belt O.C. ....	7540173	3370	6937
				Drive; W/65" Belt O.C. ....	7540191		6865
<b>136-360A</b>							
Blade .....	7540107		6830	<b>136-500</b>			
Trans. ....	7540936		6847	Blade .....	7540240		6511BR
				Transaxle .....	7540249		6930
<b>136-361</b>							
Blade .....	7540935	2310	6831	<b>136-501; 136-502; 136-503; 136-504; 136-505;</b>			
Trans. ....	7540936	2470	6847	<b>136-506; 136-507; 136-508</b>			
				Eng. To Variator .....	7540241		6494BR

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
136-501; 136-502; 136-503; 136-504; 136-505; 136-506; 136-507; 136-508 - Continued	Variator To Trans. .... 7540240		6511BR
136-510	Blade ..... 7540240		6511BR
	Transaxle ..... 7540249		6930
136-511; 136-512; 136-513; 136-514; 136-515; 136-516; 136-517; 136-518	Eng. To Variator ..... 7540241		6494BR
	Variator To Trans. .... 7540240		6511BR
136-520A; 136-525A	Blade ..... 7540195		6854
	Trans. .... 7540198		6451BR
136-526; 136-528; 136-529	Blade ..... 7540195		6854
	Deck ..... 7540195		6854
	Trans. .... 7540198		6451BR
136-610; 136-611; 136-612; 136-613; 136-614; 136-615; 136-616; 136-617	Eng. To V.S. .... 7540280A		6447BR
	V.S. To Trans. .... 7540281		6405BR
136-618	Deck ..... 7540145A		6488BR
	Eng. To V.S. .... 7540280A		6447BR
	V.S. To Trans. .... 7540281		6405BR
136-619	Deck ..... 7540271		6557BR
	Eng. To V.S. .... 7540280A		6447BR
	V.S. To Trans. .... 7540281		6405BR
136-620; 136-621; 136-622; 136-623; 136-624; 136-625; 136-626; 136-627; 136-628; 136-629	Eng. To V.S. .... 7540280A		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-630; 136-631; 136-632; 136-633; 136-634; 136-635; 136-636; 136-637	Eng. To V.S. .... 7540280A		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-638	Deck ..... 7540145A		6488BR
	Eng. To V.S. .... 7540280A		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-639	Eng. To V.S. .... 7540280A		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-640; 136-641; 136-642; 136-643; 136-644; 136-645; 136-646; 136-647; 136-648	Eng. To V.S. .... 7540280		6447BR
	V.S. To Trans. .... 7540281		6405BR
136-649	Deck ..... 7540271		6557BR
	Eng. To V.S. .... 7540280		6447BR
	V.S. To Trans. .... 7540281		6405BR
136-650; 136-651; 136-652; 136-653; 136-654; 136-655; 136-656; 136-657; 136-658; 136-659	Eng. To V.S. .... 7540280		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-660; 136-661; 136-662; 136-663; 136-664; 136-665; 136-666; 136-667; 136-668	Eng. To V.S. .... 7540280		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-669	Deck ..... 7540271		6557BR
	Eng. To V.S. .... 7540280		6447BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
136-669 - Continued	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-670; 136-671; 136-672; 136-673; 136-674; 136-675; 136-676; 136-677; 136-678	Eng. To V.S. .... 7540280		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-679	Deck ..... 7540271		6557BR
	Eng. To V.S. .... 7540280		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-680; 136-681; 136-682; 136-683; 136-684; 136-685; 136-686; 136-687; 136-688; 136-689	Eng. To V.S. .... 7540280		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-690; 136-691; 136-692; 136-693; 136-694; 136-695; 136-696; 136-697	Eng. To V.S. .... 7540280		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-698	Deck ..... 7540145A		6488BR
	Eng. To V.S. .... 7540280		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-699	Deck ..... 7540271		6557BR
	Eng. To V.S. .... 7540280		6447BR
	Transaxle ..... 7540266		6775BR
	V.S. To Trans. .... 7540281		6405BR
136-700; 136-701; 136-702; 136-703; 136-704; 136-705	V.S. To Trans. .... 7540281		6405BR
136-706; 136-707; 136-716; 136-717	Blade ..... 7540271		6557BR
136-722; 136-723; 136-724; 136-725; 136-726; 136-727	Trans. .... 7540248		6431BR
136-728; 136-729; 136-730; 136-731	Transaxle ..... 7540248		6431BR
136-732; 136-733; 136-734; 136-735; 136-736; 136-737	Trans. .... 7540248		6431BR
136-738; 136-739; 136-740; 136-741; 136-742	Transaxle ..... 7540248		6431BR
136-743	Trans. .... 7540248		6431BR
136-744	Transaxle ..... 7540248		6431BR
136-745	Trans. .... 7540248		6431BR
136-746	Transaxle ..... 7540248		6431BR
136-747	Trans. .... 7540248		6431BR
136-782	Blade ..... 7540245		6859
	Eng. To J.S. .... 7540245		6859
	J.S. To Trans. .... 7540255		6837
	Transaxle ..... 7540255		6837
136-822; 136-823; 136-824; 136-825; 136-826; 136-827; 136-828; 136-829; 136-830; 136-831	Blade ..... 7540245		6859
	Transaxle ..... 7540244		6840



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>136-832; 136-833; 136-834; 136-835; 136-836;</b>			
<b>136-837; 136-842; 136-843; 136-844; 136-845</b>			
Blade .....	7540245		6859
Transaxle .....	7540244		6840
<b>136-846; 136-847</b>			
Blade .....	7540245		6859
Transaxle .....	7540244		6840
<b>136A694F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
<b>136B560B</b>			
Blade .....	7540264		6639BR
Eng. ....	7540240		6511BR
Trans. ....	754-0241A		6494BR
<b>136C450F; 136C451F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>136E450E</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>136E450F</b>			
Blade .....	7540329A		6630BR
Eng. ....	7540280A		6447BR
Trans. ....	7540281		6405BR
<b>136E451F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>136E470E</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>136E470F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280A		6447BR
Trans. ....	7540281		6405BR
<b>136E660F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136E670G; 136G670G; 136G673G; 136G675G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136G679H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136G690G; 136G695G; 136G699G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>136G765N</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136H450E</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>136H450F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>136H451E</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>136H451F; 136H470F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>136H660F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280A		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136HE451F; 136I450F</b>			
Eng. To Deck; W/38" Deck .....	7540329A		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>136I614G</b>			
Eng. To V.S. ....	7540280		6447BR
<b>136I660F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136I660G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136I661F</b>			
Eng. To V.S. ....	7540280		6447BR
<b>136L660F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280A		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136L660G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136L661F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136L670F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280A		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136L670G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136L673F; 136L675F; 136L677F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136M660G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280A		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136M667F</b>			
Eng. To Deck .....	7540433		6630BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136M670G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280A		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136M673G; 136M675G; 136M678G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136M679G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
<b>136M695G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>136O619G; 136O660G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>136O619G; 136O660G – Continued</b>			
V.S. To Trans. ....	7540370		6439BR
<b>136O673H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136O675G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136O675H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136O695G</b>			
Blade .....	7540371		6402BR
Trans. ....	7540441		6417BR
<b>136O695H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>136O699G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>136P638</b>			
Deck .....	7540145		6488BR
<b>136P665H; 136P675H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136P695H; 136P699G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>136Q665G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136Q679H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136Q690G; 136Q695G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>136Q699H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>136S675G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>136S693H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>136S699G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>136S699H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>136X694G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>137-320</b>			
Deck .....	7540342		6868
Trans. ....	7540281		6405BR
<b>137-321; 137-322; 137-323</b>			
Deck .....	7540342		6868

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>137-324; 137-325; 137-326; 137-327; 137-328;</b>			
<b>137-329</b>			
Deck .....	7540342		6868
Eng. To Deck .....	7540342		6866
<b>137-330</b>			
Blade .....	7540107		6830
Deck .....	7540342		6868
Eng. To Deck .....	7540342		6866
<b>137-331; 137-332; 137-333; 137-334; 137-335;</b>			
<b>137-336; 137-337</b>			
Deck .....	7540342		6868
Eng. To Deck .....	7540342		6866
<b>137-340</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>137-342</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>137-360; 137-360A</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>137-362</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>137-365</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>137-380</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>137-380A; 137-385A</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>137-390</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>137-390A</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>137-391</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>137-395</b>			
Blade .....	7540118		6963
Trans. ....	7540115	3610	6961
<b>137-395A</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>137-400; 137-400A</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>137-402A</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>137-410A</b>			
Blade .....	7540138	3500	6950
<b>137-420</b>			
Blade .....	7540188		6951
Variator To Trans. ....	7540136		6931
<b>137-430A; 137-435; 137-435A</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>137-445A</b>			
Blade .....	7540178	3820	6982
Trans.; W/48" Belt O.C. ....	7540200		6848



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>137-445A - Continued</b>			
Trans., W/50" Belt O.C. ....	7540179		6950
<b>137-460</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>137-460A; 137-465A</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>137-470A; 137-475</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>137-475A</b>			
Blade .....	7540151		6967
Trans., W/65" Belt O.C. ....	7540191		6865
Trans., W/66" Belt O.C. ....	7540127		6966
<b>137-480; 137-480A; 137-485</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>137-485A</b>			
Blade .....	7540151		6967
Trans., W/65" Belt O.C. ....	7540191		6865
Trans., W/66" Belt O.C. ....	7540127		6966
<b>137-495</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>137-495A</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540191		6865
Trans. ....	7540173		6937
<b>137-496</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>137-496A</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540191		6865
Trans. ....	7540173		6937
<b>137-497</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>137-497A</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540191		6865
Trans. ....	7540173		6937
<b>137-501; 137-502; 137-503; 137-504; 137-505;</b>			
<b>137-506; 137-507; 137-508; 137-511; 137-512</b>			
Blade .....	7540118		6963
Trans. ....	7540115	3610	6961
<b>137-513; 137-514</b>			
Blade .....	7540118		6963
Trans. ....	7540115	3610	6961
<b>137-525A</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>137-526; 137-528; 137-529</b>			
Blade .....	7540195		6854
Deck .....	7540195		6854
Trans. ....	7540198		6451BR
<b>137-530; 137-531; 137-532; 137-533; 137-534;</b>			
<b>137-535; 137-536; 137-537; 137-538; 137-539</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>137-540</b>			
Deck .....	7540264		6639BR
Eng. To V.S. ....	7540280		6447BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>137-540 - Continued</b>			
V.S. To Trans. ....	7540281		6405BR
<b>137-541; 137-543; 137-544; 137-545; 137-546;</b>			
<b>137-547; 137-548; 137-549; 137-550; 137-551</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>137-552; 137-553; 137-554; 137-555; 137-556;</b>			
<b>137-557; 137-558; 137-559; 137-560; 137-561</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>137-562; 137-563; 137-564; 137-565; 137-566;</b>			
<b>137-567; 137-600; 137-601; 137-602; 137-603</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>137-604; 137-605; 137-606; 137-607; 137-608;</b>			
<b>137-609; 137-610; 137-611; 137-612; 137-613</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>137-614; 137-615; 137-616; 137-617; 137-618;</b>			
<b>137-619; 137-620; 137-621; 137-622; 137-623</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>137-624; 137-625; 137-626; 137-627; 137-628;</b>			
<b>137-629; 137-630; 137-631; 137-632; 137-633</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>137-634</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>137-635; 137-636</b>			
V.S. To Trans. ....	7540281		6405BR
<b>137-637</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>137-638; 137-639</b>			
V.S. To Trans. ....	7540281		6405BR
<b>137-640; 137-641; 137-642; 137-643; 137-644;</b>			
<b>137-645; 137-646; 137-647; 137-648; 137-649</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>137-650; 137-651; 137-652; 137-653; 137-654;</b>			
<b>137-655; 137-657</b>			
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>137-722; 137-723; 137-724; 137-725; 137-726;</b>			
<b>137-727; 137-728; 137-729; 137-730; 137-731</b>			
Trans. ....	7540248		6431BR
<b>137-732; 137-733; 137-734; 137-735; 137-736;</b>			
<b>137-737; 137-738; 137-739; 137-740; 137-741</b>			
Trans. ....	7540248		6431BR
<b>137-742; 137-743; 137-744; 137-745; 137-746;</b>			
<b>137-747; 137-748; 137-749; 137-750; 137-751</b>			
Trans. ....	7540248		6431BR
<b>137-752; 137-753; 137-754; 137-755; 137-756;</b>			
<b>137-757</b>			
Trans. ....	7540248		6431BR
<b>137-776</b>			
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540255		6837
<b>138-320; 138-321; 138-322; 138-323; 138-324;</b>			
<b>138-325; 138-326; 138-327; 138-328; 138-329</b>			
Eng. To Deck .....	7540355		6448BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>138-330; 138-331; 138-332; 138-333; 138-334; 138-335; 138-336; 138-337; 138-338; 138-339</b>			
Eng. To Deck .....	7540355		6448BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>138-340; 138-341; 138-342; 138-343; 138-344; 138-345; 138-346; 138-347; 138-348; 138-349</b>			
Eng. To Deck .....	7540355		6448BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>138-350; 138-351; 138-352; 138-353; 138-354; 138-355; 138-356; 138-357</b>			
Eng. To Deck .....	7540355		6448BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>138-360</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>138-360A</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>138-362; 138-365</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>138-380</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>138-380A; 138-385A</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>138-390</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>138-390A</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>138-392</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>138-395; 138-395A</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>138-400; 138-400A</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>138-402; 138-402A</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>138-420</b>			
Blade .....	7540127		6966
Trans. ....	7540128		6935
<b>138-420A</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>138-422</b>			
Blade .....	7540127		6966
Trans. ....	7540128		6935
<b>138-460</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>138-460A; 138-462A; 138-465A</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>138-472A; 138-475A; 138-480; 138-485A</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>138-493; 138-493A; 138-495; 138-495A; 138-496A; 138-497A</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>138-498A</b>			
Blade .....	7540225		6565
Trans. ....	7540226		6551BR
<b>138-501; 138-502; 138-503; 138-504; 138-505</b>			
Deck; W/26", 30" Deck .....	7540264		6639BR
Deck; W/32" Deck .....	7540290		6847
Drive; W/35" Belt O.C. ....	7540241		6494BR
Drive - Eng. To Variator; W/38" Belt O.C. ....	7540240		6511BR
<b>138-506</b>			
Blade .....	7540290		6847
Deck .....	7540347		6847BR
Drive; W/35" Belt O.C. ....	7540241		6494BR
Drive - Eng. To Variator; W/38" Belt O.C. ....	7540240		6511BR
<b>138-507; 138-508; 138-511; 138-512; 138-513; 138-514</b>			
Deck; W/26", 30" Deck .....	7540264		6639BR
Deck; W/32" Deck .....	7540290		6847
Drive; W/35" Belt O.C. ....	7540241		6494BR
Drive - Eng. To Variator; W/38" Belt O.C. ....	7540240		6511BR
<b>138-525; 138-525A</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>138-526; 138-528; 138-529</b>			
Deck .....	7540195		6854
Trans. ....	7540198		6451BR
<b>138-530; 138-531; 138-532; 138-533; 138-537; 138-538; 138-540; 138-541; 138-542; 138-543</b>			
Deck; W/30" Rear Discharge 794 .....	7540328		6949
Deck; W/34" Side Discharge 800 .....	7540151		6967
Deck; W/38" Side Discharge 801 .....	7540145		6488BR
Deck; W/38" Side Discharge 805 .....	7540329		6630BR
<b>138-547; 138-548; 138-560; 138-561; 138-562; 138-563; 138-567; 138-568</b>			
Deck; W/30" Rear Discharge 794 .....	7540328		6949
Deck; W/34" Side Discharge 800 .....	7540151		6967
Deck; W/38" Side Discharge 801 .....	7540145		6488BR
Deck; W/38" Side Discharge 805 .....	7540329		6630BR
<b>138-572; 138-573; 138-577; 138-578; 138-582; 138-583; 138-587; 138-588</b>			
Blade; W/40" Rear Discharge 804 .....	7540271		6557BR
Cross Drive; W/44" Side Discharge 803 .....	7540293		6501BR
Deck; W/38" Side Discharge 805 .....	7540329		6630BR
Deck; W/44" Side Discharge 803 .....	7540229		6852
<b>138-600; 138-601; 138-602; 138-603; 138-607; 138-608; 138-610; 138-611; 138-612; 138-613</b>			
Deck; W/30" Rear Discharge 794 .....	7540328		6949
Deck; W/34" Side Discharge 800 .....	7540151		6967
Deck; W/38" Side Discharge 801 .....	7540145		6488BR
Deck; W/38" Side Discharge 805 .....	7540329		6630BR
<b>138-617; 138-618; 138-622; 138-630; 138-631; 138-632; 138-633; 138-637; 138-638; 138-640</b>			
Deck; W/30" Rear Discharge 794 .....	7540328		6949
Deck; W/34" Side Discharge 800 .....	7540151		6967
Deck; W/38" Side Discharge 801 .....	7540145		6488BR
Deck; W/38" Side Discharge 805 .....	7540329		6630BR
<b>138-641; 138-642; 138-643; 138-647; 138-648; 138-650; 138-651; 138-652; 138-653; 138-657</b>			
Deck; W/30" Rear Discharge 794 .....	7540328		6949
Deck; W/34" Side Discharge 800 .....	7540151		6967
Deck; W/38" Side Discharge 801 .....	7540145		6488BR
Deck; W/38" Side Discharge 805 .....	7540329		6630BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>138-658</b>			
Deck; W/30" Rear Discharge 794 .....	7540328		6949
Deck; W/34" Side Discharge 800 .....	7540151		6967
Deck; W/38" Side Discharge 801 .....	7540145		6488BR
Deck; W/38" Side Discharge 805 .....	7540329		6630BR
<b>138-662; 138-663; 138-667; 138-668; 138-672; 138-673; 138-677; 138-678; 138-682; 138-683</b>			
Blade; W/40" Rear Discharge 804 .....	7540271		6557BR
Cross Drive; W/44" Side Discharge 803 .....	7540293		6501BR
Deck; W/38" Side Discharge 805 .....	7540329		6630BR
Deck; W/44" Side Discharge 803 .....	7540229		6852
<b>138-687; 138-688; 138-692; 138-693; 138-697; 138-698</b>			
Blade; W/40" Rear Discharge 804 .....	7540271		6557BR
Cross Drive; W/44" Side Discharge 803 .....	7540293		6501BR
Deck; W/38" Side Discharge 805 .....	7540329		6630BR
Deck; W/44" Side Discharge 803 .....	7540229		6852
<b>138-722; 138-723</b>			
Cross Drive; W/44" Side Discharge 935 .....	7540293		6501BR
Cross Drive; W/46" Side Discharge 806 .....	7540349		6637BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Rear Discharge 935 .....	7540230		6755BR
Deck; W/46" Side Discharge 806 .....	7540350		6464BR
Trans. ....	7540248		6431BR
<b>138-724; 138-725; 138-726</b>			
Transaxle .....	7540248		6431BR
<b>138-727; 138-728</b>			
Cross Drive; W/44" Side Discharge 935 .....	7540293		6501BR
Cross Drive; W/46" Side Discharge 806 .....	7540349		6637BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Rear Discharge 935 .....	7540230		6755BR
Deck; W/46" Side Discharge 806 .....	7540350		6464BR
Trans. ....	7540248		6431BR
<b>138-729; 138-730; 138-731</b>			
Transaxle .....	7540248		6431BR
<b>138-732; 138-733</b>			
Cross Drive; W/44" Side Discharge 935 .....	7540293		6501BR
Cross Drive; W/46" Side Discharge 806 .....	7540349		6637BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Rear Discharge 935 .....	7540230		6755BR
Deck; W/46" Side Discharge 806 .....	7540350		6464BR
Trans. ....	7540248		6431BR
<b>138-734; 138-735; 138-736</b>			
Transaxle .....	7540248		6431BR
<b>138-737; 138-738</b>			
Cross Drive; W/44" Side Discharge 935 .....	7540293		6501BR
Cross Drive; W/46" Side Discharge 806 .....	7540349		6637BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Rear Discharge 935 .....	7540230		6755BR
Deck; W/46" Side Discharge 806 .....	7540350		6464BR
Trans. ....	7540248		6431BR
<b>138-739; 138-740; 138-741</b>			
Transaxle .....	7540248		6431BR
<b>138-742; 138-743</b>			
Cross Drive; W/44" Side Discharge 935 .....	7540293		6501BR
Cross Drive; W/46" Side Discharge 806 .....	7540349		6637BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Rear Discharge 935 .....	7540230		6755BR
Deck; W/46" Side Discharge 806 .....	7540350		6464BR
Trans. ....	7540248		6431BR
<b>138-744; 138-745; 138-746</b>			
Transaxle .....	7540248		6431BR
<b>138-747; 138-748</b>			
Cross Drive; W/44" Side Discharge 935 .....	7540293		6501BR
Cross Drive; W/46" Side Discharge 806 .....	7540349		6637BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Rear Discharge 935 .....	7540230		6755BR
Deck; W/46" Side Discharge 806 .....	7540350		6464BR
Trans. ....	7540248		6431BR
<b>138-749; 138-750; 138-751</b>			
Transaxle .....	7540248		6431BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>138-752; 138-753</b>			
Cross Drive; W/44" Side Discharge 935 .....	7540293		6501BR
Cross Drive; W/46" Side Discharge 806 .....	7540349		6637BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Rear Discharge 935 .....	7540230		6755BR
Deck; W/46" Side Discharge 806 .....	7540350		6464BR
Trans. ....	7540248		6431BR
<b>138-754; 138-755</b>			
Transaxle .....	7540248		6431BR
<b>138-757; 138-758</b>			
Cross Drive; W/44" Side Discharge 935 .....	7540293		6501BR
Cross Drive; W/46" Side Discharge 806 .....	7540349		6637BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Rear Discharge 935 .....	7540230		6755BR
Deck; W/46" Side Discharge 806 .....	7540350		6464BR
Trans. ....	7540248		6431BR
<b>138-784; 138-786</b>			
Blade .....	7540245		6859
Cross Drive; W/44" Rear Discharge 931 .....	7540260		5716
Cross Drive; W/44" Side Discharge 935 .....	7540293		6501BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Side Discharge 935 .....	7540230		6755BR
Deck; W/46" Side Discharge 806 .....	7540350		6464BR
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540255		6837
Transaxle .....	7540255		6837
<b>138-793; 138-795</b>			
Deck .....	7540254		6819
<b>138-796</b>			
Blade .....	7540198		6451BR
Deck .....	7540254		6819
Trans. ....	7540207		6842
<b>138-796A; 138-797A</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>139-330</b>			
Trans. ....	7540140		6831
<b>139-340; 139-360</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>139-360A</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>139-365</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>139-380A</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>139-390</b>			
Blade .....	7540105		6830
Trans. ....	7540111	2450	6845
<b>139-390A; 139-395; 139-395A</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>139-400; 139-400A</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>139-402; 139-402A</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>139-410</b>			
Blade .....	7540138	3500	6950
<b>139-420; 139-430</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>139-460</b>			
Blade .....	7540118		6963
Gen. ....	7540134		6733
Trans. ....	7540937	3590	6959
<b>139-465; 139-466</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>139-470</b>			
Blade .....	7540118		6963
Gen. ....	7540134		6733
Trans. ....	7540937	3590	6959
<b>139-485A</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>139-493A; 139-495A; 139-496; 139-496A;</b>			
<b>139-497; 139-497A; 139-498; 139-498A</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>139-501; 139-502; 139-503; 139-504; 139-505;</b>			
<b>139-506; 139-507; 139-508; 139-511; 139-512</b>			
Blade .....	7540118		6963
Trans. ....	7540115	3610	6961
<b>139-513; 139-514</b>			
Blade .....	7540118		6963
Trans. ....	7540115	3610	6961
<b>139-525; 139-525A</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>139-526</b>			
Trans. ....	7540198		6451BR
<b>139-752; 139-753; 139-757; 139-758</b>			
Eng. To Trans. ....	7540116		6842
<b>139-784</b>			
Variable Speed .....	7540365		6798BR
<b>139-794</b>			
Blade .....	7540328		6949
<b>139-796; 139-796A</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>139-800; 139-801; 139-802; 139-803; 139-804;</b>			
<b>139-805; 139-806; 139-807; 139-808; 139-809</b>			
Blade .....	7540349		6637BR
Deck .....	7540350		6464BR
Variable Speed .....	7540248		6431BR
<b>139-810; 139-811; 139-812; 139-813; 139-814;</b>			
<b>139-815; 139-816; 139-817; 139-818; 139-819</b>			
Blade .....	7540349		6637BR
Deck .....	7540350		6464BR
Variable Speed .....	7540248		6431BR
<b>139-820; 139-821; 139-822; 139-823; 139-824;</b>			
<b>139-825; 139-826; 139-827; 139-828; 139-829</b>			
Blade .....	7540349		6637BR
Deck .....	7540350		6464BR
Variable Speed .....	7540248		6431BR
<b>139-830; 139-831; 139-832; 139-833; 139-834;</b>			
<b>139-835; 139-836; 139-837; 139-838; 139-839</b>			
Blade .....	7540349		6637BR
Deck .....	7540350		6464BR
Variable Speed .....	7540248		6431BR
<b>139-840; 139-841; 139-842; 139-843; 139-844;</b>			
<b>139-845; 139-846; 139-847; 139-848; 139-849</b>			
Blade .....	7540349		6637BR
Deck .....	7540350		6464BR
Variable Speed .....	7540248		6431BR
<b>140-520</b>			
Blade .....	7540230		6755BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>140-520 - Continued</b>			
Trans. ....	7540245		6859
<b>140-650</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>140-659; 140-669</b>			
Blade .....	7540113	3480	6948
Gen. ....	7540134	7330	
Trans. ....	7540112		6980
<b>140-760</b>			
Blade .....	7540125		6428BR
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>140-760A</b>			
Trans. ....	7540245		6859
<b>140-780A</b>			
Blade .....	7540230		6755BR
Trans. ....	7540245		6859
<b>140-810</b>			
Drive .....	7540245		6859
Transaxle .....	7540243		6846
<b>140-810A</b>			
Drive .....	7540245		6859
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540243		6846
Transaxle .....	7540243		6846
<b>140-820A</b>			
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540244		6840
<b>140-820H</b>			
Eng. To Deck .....	7540350		6464BR
<b>140-830A</b>			
Drive .....	7540227		6963
J.S. ....	7540245		6859
Trans. ....	7540244		6840
Transaxle .....	7540212		6945
<b>140-840H; 140-844H; 140-848H; 140-849H</b>			
Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>140-912A</b>			
Drive .....	7540227		6963
Transaxle .....	7540212		6945
<b>140-918</b>			
Drive .....	7540227		6963
<b>140-918A</b>			
Drive .....	7540227		6963
Transaxle .....	7540212		6945
<b>140-940</b>			
P.T.O. ....	7540192		6834
<b>140-960</b>			
Blade .....	7540125		6428BR
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>140-990; 140-990A</b>			
P.T.O. ....	7540165		6834
<b>140-995A</b>			
P.T.O. ....			6841
<b>141-659; 141-669</b>			
Gen. ....	7540134	7330	
Starter/Gen. ....	7540134		6733
Trans. ....	7540112	3800	6980
<b>141-760</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
141-810H; 141-811H; 141-812H; 141-813H; 141-814H; 141-815H; 141-816H; 141-817H; 141-818H; 141-819H Cross Deck .....	7540349		6637BR
141-820H; 141-821H; 141-822H; 141-823H Cross Deck .....	7540349		6637BR
141-824A Deck .....	7540230		6755BR
J.S. ....	7540245		6859
Transaxle .....	7540244		6840
141-824H; 141-825H; 141-826H; 141-827H; 141-828H; 141-829H; 141-830H; 141-831H; 141-832H; 141-833H Cross Deck .....	7540349		6637BR
141-834H; 141-835H; 141-836H; 141-837H; 141-838H; 141-839H Cross Deck .....	7540349		6637BR
141-840H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
141-841 Eng. To V.S. ....	7540358		6419BR
141-841H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
141-842 Eng. To V.S. ....	7540358		6419BR
141-842H; 141-843H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
141-844 Eng. To V.S. ....	7540358		6419BR
141-844H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
141-845 Eng. To V.S. ....	7540358		6419BR
141-845H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
141-846 Eng. To V.S. ....	7540358		6419BR
141-846H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
141-847 Eng. To V.S. ....	7540358		6419BR
141-847H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
141-848 Eng. To V.S. ....	7540358		6419BR
141-848H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
141-849 Eng. To V.S. ....	7540358		6419BR
141-849H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
141-860 P.T.O. ....	7540123		3V335
Trans. ....	7540112	3800	6980
141-960 P.T.O. ....	7540123		3V335

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
141-960 - Continued Trans. ....	7540124		6857
141-990 P.T.O. ....	7540123		3V335
141-990A Drive .....	7540124		6857
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
141-995A P.T.O. ....	7540234		6841
142-46H Eng. To V.S. ....	7540358		6419BR
142-669 Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
142-760 Drive .....	7540124		6857
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
142-810 Belt; W/51" Belt O.C. ....	7540251		6809BR
Belt; W/53" Belt O.C. ....	7540250	2530	
142-824 Blade .....	7540246		6354
Deck .....	7540230		6755BR
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540244		6840
142-836 Blade .....	7540230		6755BR
Deck .....	7540246		6354
Drive; W/40" Belt O.C. ....	7540244		6840
Drive; W/59" Belt O.C. ....	7540245		6859
142-840H Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
142-846H Cross Deck .....	7540349		6637BR
142-848H Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
142-849H Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
142-960 Drive .....	7540124		6857
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
142-990 P.T.O. ....	7540165		6834
142-995 Belt .....	7540234		6841
143-660 Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
143-760 Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
143-814 Blade .....	7540230		6755BR
Deck .....	7540246		6354
Trans. ....	7540245		6859
Transaxle .....	7540244		6840

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>143-836</b>			
Eng. To Deck .....	7540230		6755BR
Eng. To J.S. ....	7540245		6859
J.S. To Transaxle .....	7540244		6840
<b>143-860; 143-960</b>		7380	
Drive .....	7540124		6857
Gen. ....	7540139		6834
P.T.O. ....	7540165		6834
<b>143-990</b>		7355	
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540169		6857
Transaxle .....	7540124		6841
<b>143-995</b>			
P.T.O. ....	7540234		6841
<b>143P820H</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>143P828H</b>			
Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>143P840H; 143P848H; 143P849H</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>143Q840H</b>			
Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>143Q848H</b>			
Eng. To V.S. ....	7540358		6419BR
<b>143V834H; 143W834H; 143Y839H</b>			
Cross Deck .....	7540349		6637BR
<b>143Y849H</b>			
Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>144-485</b>		3810	
Blade .....	7540184		6852
Eng. To Deck .....	7540180		6510BR
Trans. ....	7540182		6981
<b>144-600; 144-601; 144-602</b>		7330	
Gen. ....	7540134		6981
<b>144-660A</b>		7330	
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134		6981
Trans. ....	7540182		6981
<b>144-672A</b>		3810	
Blade .....	7540184		6852
Eng. To Deck .....	7540180		6510BR
Trans. ....	7540182		6981
<b>144-760A; 144-761A</b>		3810	
Trans. ....	7540182		6981
<b>144-810; 144-811; 144-824; 144-825</b>			
Blade .....	7540245		6859
Eng. To Variator .....	7540245		6859
Transaxle .....	7540244		6840
Variator To Trans. ....	7540244		6840
<b>144-825H; 144-829H</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>144-834; 144-835; 144-836; 144-837</b>			
Blade .....	7540245		6859
Transaxle .....	7540244		6840

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>144-860A</b>			
P.T.O. ....	7540165		6834
Transaxle .....	7540124		6857
<b>144-918</b>			
Eng. To Variator .....	7540212		6945
Variator To Trans. ....	7540227		6963
<b>144-960A; 144-990A</b>			
P.T.O. ....	7540165		6834
Transaxle .....	7540124		6857
<b>144-995</b>			
Drive .....	7540234		6841
<b>144O845H</b>			
Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>144P820H; 144P828H</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>144P840H</b>			
Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>144P849H</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>144Q828H</b>			
Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>144Q840H</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>144Q845H</b>			
Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>144Q848H</b>			
Cross Deck .....	7540349		6637BR
Eng. To Deck .....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>144V834H</b>			
Cross Deck .....	7540349		6637BR
<b>144W834P; 144Z834P</b>			
Cross Deck .....	7540291A		6641BR
Drive .....	7540435		A72
Eng. To Deck .....	7540364		6482BR
<b>145-660</b>			
Blade .....	7540184		6852
<b>145-660A</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>145-672</b>			
Blade .....	7540184		6852
Eng. To Deck .....	7540180		6510BR
Trans. ....	7540182	3810	6981
<b>145-672A</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>145-760</b>			
Trans. ....	7540182	3810	6981



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>145-760A</b>			
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>145-810; 145-811; 145-822; 145-823; 145-824;</b>			
<b>145-825; 145-826; 145-827; 145-832; 145-833</b>			
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>145-834</b>			
Belt; W/40" Belt O.C. ....	7540244		6840
Trans.; W/56" Belt O.C. ....	7540230		6755BR
Trans.; W/59" Belt O.C. ....	7540245		6859
Trans.; W/74" Belt O.C. ....	7540293		6501BR
<b>145-835; 145-836; 145-837</b>			
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>145-842; 145-843</b>			
Trans.; W/32" Belt O.C. ....	7540177		6832
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>145-918</b>			
Drive ....	7540227		6963
P.T.O. ....	7540229		6852
Transaxle ....	7540212		6945
<b>145-960; 145-960A</b>			
Gen. ....	7540169	7355	
P.T.O. ....	7540165		6834
Transaxle ....	7540124		6857
<b>145-990</b>			
P.T.O. ....	7540165		6834
Transaxle ....	7540124		6857
<b>145-990A</b>			
Gen. ....	7540169		6736
P.T.O. ....	7540165		6834
<b>145-995</b>			
Deck ....	7540180		6510BR
Starter/Gen. ....	7540134	7330	
Trans.; W/41" Belt O.C. ....	7540234		6841
Trans.; W/81" Belt O.C. ....	7540182	3810	6981
<b>145J828P</b>			
Cross Deck ....	7540291A		6641BR
Eng. To Deck ....	7540364		6482BR
Eng. To V.S. ....	7540358		6419BR
V.S. To Trans. ....	7540362		6984BR
<b>145-J828P</b>			
Eng. To V.S. ....	7540358		6419BR
<b>145P820H</b>			
Cross Deck ....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>145P828H; 145P845H</b>			
Cross Deck ....	7540349		6637BR
Eng. To Deck ....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>145P848H</b>			
Deck; W/64" Belt O.C. ....	7540350		6464BR
Deck; W/79" Belt O.C. ....	7540349		6637BR
Eng. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>145Q828H; 145Q840H; 145Q848H</b>			
Cross Deck ....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>145Q849H</b>			
Cross Deck ....	7540349		6637BR
Eng. To Deck ....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>145S820H; 145S845H; 145S848H</b>			
Eng. To V.S. ....	7540358		6419BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>145V848H</b>			
Cross Deck ....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>145W820H</b>			
Cross Deck ....	7540349		6637BR
<b>145W834P</b>			
Cross Deck ....	7540291A		6641BR
Drive ....	7540435		A72
Eng. To Deck ....	7540364		6482BR
<b>145W845H; 145W848H</b>			
Cross Deck ....	7540349		6637BR
<b>145Y834P</b>			
Cross Deck ....	7540291A		6641BR
Drive ....	7540435		A72
Eng. To Deck ....	7540364		6482BR
<b>146-650; 146-660</b>			
Trans. ....	7540112	3800	6980
<b>146-660A</b>			
Blade ....	7540184		6852
Deck ....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>146-672A</b>			
Blade ....	7540184		6852
Eng. To Deck ....	7540180		6510BR
Trans. ....	7540182	3810	6981
<b>146-760</b>			
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>146-822; 146-823; 146-824; 146-825; 146-826;</b>			
<b>146-827; 146-831; 146-832; 146-833; 146-834</b>			
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>146-835; 146-836; 146-837</b>			
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>146-842; 146-843; 146-844; 146-845; 146-846;</b>			
<b>146-847</b>			
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540177	2320	6832
<b>146-960A</b>			
P.T.O. ....	7540165		6834
Transaxle ....	7540124		6857
<b>146-990A</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540169		6736
<b>146-995</b>			
P.T.O. ....	7540234		6841
<b>146K828H</b>			
Cross Deck ....	7540349		6637BR
Eng. To Deck ....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>146K840H</b>			
Cross Deck ....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>146K848H</b>			
Cross Deck ....	7540349		6637BR
Eng. To Deck ....	7540350		6464BR
Eng. To V.S. ....	7540358		6419BR
Trans. ....	7540361		6953
<b>146P820H; 146P828H; 146Q828H; 146S820H;</b>			
<b>146S828H; 146S843H; 146S845H; 146S848H;</b>			
<b>146S849H</b>			
Cross Deck ....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>146W834H</b>			
Cross Deck .....	7540349		6637BR
<b>146Y834P</b>			
Cross Deck .....	7540291A		6641BR
Drive .....	7540461		6519BR
Eng. To Deck .....	7540364		6482BR
<b>147-652; 147-655; 147-660; 147-665</b>			
Trans. ....	7540112	3800	6980
<b>147-760; 147-760A</b>			
Starter/Gen. ....	7540134		6733
Transaxle .....	7540182		6981
<b>147-802; 147-803; 147-804; 147-805; 147-806;</b>			
<b>147-807; 147-808; 147-809; 147-810; 147-811</b>			
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>147-812; 147-813; 147-814; 147-815; 147-816;</b>			
<b>147-817; 147-818; 147-819; 147-820; 147-821</b>			
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>147-822; 147-823; 147-824; 147-825; 147-826;</b>			
<b>147-827</b>			
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>147-842; 147-843; 147-844; 147-845; 147-846;</b>			
<b>147-847; 147-848; 147-849; 147-850; 147-851</b>			
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540177	2320	6832
<b>147-852; 147-853; 147-854; 147-855; 147-856;</b>			
<b>147-857; 147-858; 147-859; 147-860</b>			
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540177	2320	6832
<b>147-860A</b>			
Trans. ....	7540217		6979
<b>147-861; 147-862; 147-863; 147-864; 147-865;</b>			
<b>147-866; 147-867</b>			
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540177	2320	6832
<b>147-910A</b>			
Eng. To Transaxle .....	7540211		6946
Primary .....	7540228		6962
<b>147-912</b>			
Drive .....	7540210		6960
Trans. ....	7540212		6945
<b>147-912A</b>			
Belt; W/60" Belt O.C. ....	7540210		6960
Belt; W/63" Belt O.C. ....	7540227		6963
Trans. ....	7540212		6945
<b>147-916A</b>			
Eng. To Transaxle .....	7540211		6946
Primary .....	7540228		6962
<b>147-918</b>			
Drive .....	7540210		6960
Trans. ....	7540212		6945
<b>147-918A</b>			
Belt; W/60" Belt O.C. ....	7540210		6960
Belt; W/63" Belt O.C. ....	7540227		6963
Trans.; W/45" Belt O.C. ....	7540212		6945
<b>147-990A</b>			
Gen. ....	7540169		6736
P.T.O. ....	7540165		6834
<b>147-995</b>			
P.T.O. ....	7540234		6841
<b>147W834H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540461		6519BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>147Y834P</b>			
Drive .....	7540461		6519BR
<b>148-650; 148-655; 148-658; 148-659; 148-660;</b>			
<b>148-665; 148-668; 148-669</b>			
Trans. ....	7540112	3800	6980
<b>148-760</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
P.T.O. ....	7540123		3V335
Trans. ....	7540124	2570	6857
<b>148-760A</b>			
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>148-802; 148-803</b>			
Cross Drive; W/44" Side Discharge 935 ..	7540293		6501BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Side Discharge 935 .....	7540230		6755BR
Trans.; W/32" Belt O.C. ....	7540177	2320	6832
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>148-806</b>			
Cross Deck .....	7540349		6637BR
<b>148-807; 148-808; 148-812; 148-813</b>			
Cross Drive; W/44" Side Discharge 935 ..	7540293		6501BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Side Discharge 935 .....	7540230		6755BR
Trans.; W/32" Belt O.C. ....	7540177	2320	6832
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>148-815</b>			
Eng. To Spindle .....	7540229		6852
Spindle To Rear Tiller .....	7540283		6895
<b>148-817; 148-818; 148-822; 148-823; 148-827;</b>			
<b>148-828; 148-842; 148-847; 148-852; 148-857</b>			
Cross Drive; W/44" Side Discharge 935 ..	7540293		6501BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Side Discharge 935 .....	7540230		6755BR
Trans.; W/32" Belt O.C. ....	7540177	2320	6832
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>148-860</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
Transaxle .....	7540124		6857
<b>148-860A</b>			
Trans. ....	7540217		6979
<b>148-862; 148-867</b>			
Cross Drive; W/44" Side Discharge 935 ..	7540293		6501BR
Deck; W/44" Rear Discharge 931 .....	7540230		6755BR
Deck; W/44" Side Discharge 935 .....	7540230		6755BR
Trans.; W/32" Belt O.C. ....	7540177	2320	6832
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>148-910A</b>			
Eng. To Transaxle .....	7540211		6946
Primary .....	7540228		6962
<b>148-912A</b>			
Belt; W/60" Belt O.C. ....	7540210		6960
Belt; W/63" Belt O.C. ....	7540227		6963
Trans. ....	7540212		6945
<b>148-916A</b>			
Eng. To Transaxle .....	7540211		6946
Primary .....	7540228		6962
<b>148-918</b>			
Drive .....	7540227		6963
Transaxle .....	7540212		6945
<b>148-918A</b>			
Belt; W/60" Belt O.C. ....	7540210		6960
Belt; W/63" Belt O.C. ....	7540227		6963



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>148-918A - Continued</b>			
Trans. ....	7540212		6945
<b>148-990A</b>			
Gen. ....	7540136		6736
P.T.O. ....	7540135		6834
<b>149-760</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>149-761</b>			
Mower; W/42" Deck .....	7540125		6428BR
<b>149-805</b>			
Eng. To Deck .....	7540329		6630BR
<b>149-810; 149-810A</b>			
Drive .....	7540245		6859
Transaxle .....	7540243		6846
<b>149-812</b>			
Eng. To V.S. ....	7540358		6419BR
<b>149-813</b>			
Eng. To V.S. ....	7540358		6419BR
Transaxle .....	7540248		6431BR
<b>149-815; 149-816; 149-818; 149-819</b>			
Eng. To V.S. ....	7540358		6419BR
<b>149-820; 149-820A</b>			
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>149-821; 149-822; 149-823; 149-825; 149-826;</b>			
<b>149-828; 149-829</b>			
Eng. To V.S. ....	7540358		6419BR
<b>149-836</b>			
Blade .....	7540364		6482BR
<b>149-844</b>			
Blade .....	7540260		5716
<b>149-846</b>			
Blade .....	7540349		6637BR
Deck .....	7540350		6464BR
<b>149-860</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>149-910A</b>			
Eng. To Transaxle .....	7540211		6946
Primary .....	7540228		6962
<b>149-912A</b>			
Belt; W/60" Belt O.C. ....	7540210		6960
Belt; W/63" Belt O.C. ....	7540227		6963
Trans. ....	7540212		6945
<b>149-916A</b>			
Eng. To Transaxle .....	7540211		6946
Primary .....	7540228		6962
<b>149-918</b>			
Drive .....	7540227		6963
Transaxle .....	7540212		6945
<b>149-918A</b>			
Belt; W/60" Belt O.C. ....	7540210		6960
Belt; W/63" Belt O.C. ....	7540227		6963
Trans. ....	7540212		6945
<b>149-990; 149-990A</b>		7355	
Gen. ....	7540169		6834
P.T.O. ....	7540165		
<b>149-995; 149-995A</b>			
P.T.O. ....	7540234		6841
<b>179-812; 190-840</b>			
Eng. To V.S. ....	7540358		6419BR
<b>190-846</b>			
Cross Deck .....	7540349		6637BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>223-0705</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>223-3188</b>			
Blade .....	7540188		6951
Drive .....	7540136		6931
<b>223-3189</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>223-3219</b>			
Blade .....	7540138	3500	6950
<b>223-3220</b>			
Blade .....	7540147	3520	6952
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>223-3221</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>223-3222</b>			
Blade .....	7540145		6488BR
Trans.; W/31" Belt O.C. ....	7540136		6931
Trans.; W/52" Belt O.C. ....	7540147	3520	6952
<b>223-3230</b>			
Gen. ....	7540134		6733
Transaxle .....	7540112		6980
<b>223-3231</b>			
P.T.O. ....	7540123		3V335
Transaxle .....	7540124		6857
<b>223-3233</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>223-3234</b>			
Blade; W/50" Belt O.C. ....	7540138	3500	6950
Blade; W/52" Belt O.C. ....	7540147	3520	6952
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
Trans.; W/35" Belt O.C. ....	7540101		6517BR
<b>223-3236</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>223-3237; 223-3238</b>			
Blade .....	7540151		6967
Trans.; W/31" Belt O.C. ....	7540136		6931
Trans.; W/50" Belt O.C. ....	7540138		6950
<b>223-3241</b>			
Gen. ....	7540134		6733
Transaxle .....	7540112		6980
<b>223-3247</b>			
Drive .....	7540124		6857
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
<b>223-3250</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>223-3251</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>223-3255</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>223-3256</b>			
Blade .....	7540188		6951

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>223-3256 - Continued</b>			
Trans .....	7540101		6517BR
<b>223-3260</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>223-3268</b>			
Drive .....	7540124		6857
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
<b>223-3279</b>			
Blade .....	7540118		6963
Transaxle .....	7540937		6959
<b>223-3289</b>			
P.T.O. ....	7540123		3V335
Transaxle .....	7540124		6857
<b>223-3291</b>			
Blade .....	7540127		6966
Trans. ....	7540128		6935
<b>223-3404</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>223-3406</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>223-3414</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>223-3426</b>			
Trans. ....	7540164	2630	6863
<b>223-3427</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>223-3428</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>223-7920</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>223-7921</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>223-7922</b>			
Blade .....	7540188		6951
Transaxle .....	7540136		6931
<b>223-8020</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>223-8021</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>223-8022</b>			
Blade .....	7540188		6951
Transaxle .....	7540136		6931
<b>223-8420</b>			
Blade .....	7540241		6494BR
Deck .....	7540264		6639BR
Trans. ....	7540240		6511BR
<b>223-8421</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>223-8521; 223-8541</b>			
V.S. To Trans. ....	7540281		6405BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>340-129; 360-129; 360-131; 360-508</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>380-131; 380-229; 390-508</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>443-36</b>			
Trans. ....	7540936		6847
<b>481-3762; 481-3812; 481-3879</b>			
V.S. To Trans. ....	7540281		6405BR
<b>643-0724</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>643-0761</b>			
Blade .....	7540107		6830
<b>643-762</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>643-0766</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>643-0837</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>643-0838; 643-0839</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>643-0840</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>643-0845; 643-0846</b>			
Blade .....	7540145		6488BR
Trans.; W/31" Belt O.C. ....	7540136		6931
Trans.; W/52" Belt O.C. ....	7540147	3520	6952
<b>643-0848; 643-0851</b>			
Blade .....	7540138	3500	6950
<b>643-0852</b>			
Blade .....	7540107		6830
Trans. ....	7540111	2450	6845
<b>643-0853; 643-0854</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>643-0855; 643-0856</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>643-858</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>643-0859; 643-0860</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>643-0861</b>			
Blade .....	7540147	3520	6952
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>643-0862; 643-0863</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>643-0864</b>			
Blade .....	7540147	3520	6952
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>643-0865; 643-0866; 643-0868</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>643-0869</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>643-0873; 643-0874</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>643-884</b>		3500	
Blade .....	7540138		6950
Trans. ....	7540101		6517BR
<b>643-2160; 643-2161</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>643-2163</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>643-2164</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>643-2165</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>643-2166</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>643-2170</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540164	2630	6863
<b>643-2171</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>643-2172</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540108	2460	6846
<b>643-2173</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>643-2182</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540136		6931
<b>643-2190</b>			
Blade .....	7540145		6488BR
Trans. ....	7540127		6966
<b>643-2191; 643-2192</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>643-4101</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>643-4102</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>643-4103; 643-4104</b>			
Deck .....	7540113	3480	6948
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>643-4105; 643-4106</b>			
Blade .....	7540125		6428BR
Gen. ....	7540134	7330	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>643-4105; 643-4106 - Continued</b>			
P.T.O. ....	7540123		3V335
<b>643-4107</b>			
Blade .....	7540184		6852
Eng. To Deck .....	7540180		6510BR
Trans. ....	7540182	3810	6981
<b>643-4108</b>			
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>643-4110</b>			
Gen. ....	7540169	7355	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>643-5106</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>643A-762; 643A-0850</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>912-918</b>			
P.T.O. ....	7540214		6850
<b>1112H</b>			
Deck .....			6978
<b>3261-01</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>3309-01; 3309-91</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>3340-41</b>			
Blade; W/30" Blade .....	7540167		6964
Blade; W/36" Blade .....	7540279		6965
Transaxle .....	7540198		6451BR
<b>3341-01; 3342-01</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>3380-51</b>			
V.S. To Trans. ....	7540281		6405BR
<b>3383-01; 3383-91; 3384-91</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>3386-4</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>3386-51</b>			
V.S. To Trans. ....	7540281		6405BR
<b>3441-01</b>			
Blade .....	7540230		6755BR
Trans. ....	7540245		6859
Transaxle .....	7540255		6837
<b>3441-51; 4144; 4173</b>			
V.S. To Trans. ....	7540281		6405BR
<b>4187-41</b>			
P.T.O. ....	7540234		6841
<b>4259</b>			
V.S. To Trans. ....	7540281		6405BR
<b>6113</b>			
Blade .....	7540138	3500	6950
<b>6132</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>6133</b>			
Blade .....	7540138	3500	6950

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>6134</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>6200; 6201</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>6210; 6211</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>6287</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>6301; 6302</b>			
Drive .....	7540124		6857
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
<b>6415</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>6416</b>			
Blade .....	7540138	3500	6950
<b>6417</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>6418; 6419</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>6420</b>			
Trans. ....	7540182	3810	6981
<b>6421</b>			
Drive .....	7540124		6857
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
<b>6473</b>			
Blade .....	7540188		6951
Transaxle .....	7540101		6517BR
<b>6475</b>			
Blade .....	7540188		6951
Drive; W/24" Belt O.C. ....	7540187	3240	6924
Drive; W/31" Belt O.C. ....	7540136		6931
<b>6490</b>			
Gen. ....	7540169	7355	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>6538</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>6544</b>			
Trans. ....	7540182	3810	6981
<b>6882</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>6885</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>7109A78</b>			
Blade .....	7540151		6967
<b>7112A78</b>			
Blade .....	7540145		6488BR
<b>7115A78</b>			
Blade; W/52" Belt O.C. ....	7540229		6852
Blade; W/74" Belt O.C. ....	7540293		6501BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>7360</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936	2470	6847
<b>7390</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>7395</b>			
Blade .....	7540118		6963
Transaxle .....	7540115		6961
<b>13327-9; 13357-9</b>			
Eng. To Deck .....	7540355		6448BR
<b>13565-7; 13565-8; 13619S</b>			
Blade - Right .....	7540271		6557BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>13637-8; 13637-9</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR
<b>13649C</b>			
Blade - Right .....	7540271		6557BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>13655-7; 13655-8; 13655-9; 13665-7; 13665-8; 13665-9</b>			
Eng. To Deck; W/38" Deck .....	7540329		6630BR
<b>13735-9; 13765-9</b>			
Cross Deck .....	7540349		6637BR
<b>14815-9</b>			
Cross Deck .....	7540349		6637BR
Eng. To V.S. ....	7540358		6419BR
<b>19806-8</b>			
Cross Deck .....	7540349		6637BR
<b>19993C; 19993S</b>			
Cross Deck .....	7540197		6604BR
<b>50041</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>50467</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>50637</b>			
Blade .....	7540241		6494BR
Deck .....	7540264		6639BR
Trans. ....	7540240		6511BR
<b>50638</b>			
Drive .....	7540151		6967
<b>50639</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>50641</b>			
Trans.; W/40" Belt O.C. ....	7540244		6840
Trans.; W/59" Belt O.C. ....	7540245		6859
<b>50723</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>50741</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>50747</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>50748</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>50749</b>			
Blade .....	7540195		6854



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>50749 – Continued</b>			
Trans. ....	7540198		6451BR
<b>50754; 50755</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>50840</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>50842</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>1340675G</b>			
Deck .....	7540371A		6402BR
Eng. ....	7540280		6447BR
Trans. ....	7540370		6439BR
<b>1361614G</b>			
Eng. To Deck .....	7540371A		6402BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540370		6439BR
<b>1362694G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>1363694H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
<b>1366693G</b>			
Eng. To Deck .....	7540371A		6402BR
<b>1463834P</b>			
Cross Deck .....	7540291A		6641BR
Drive .....	7540435		A72
Eng. To Deck .....	7540364		6482BR
<b>1465828P</b>			
Cross Deck .....	7540291A		6641BR
Eng. To Deck .....	7540364		6482BR
Eng. To V.S. ....	7540358		6419BR
V.S. To Trans. ....	7540362		6984BR
<b>FC106</b>			
Trans. ....	7540182	3810	6981
<b>FC166</b>			
P.T.O. ....	7540165		6834
Trans. ....	7540124	2570	6857
<b>FC506</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>FC525</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>FC526</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>FC805</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>FC806</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>FC826</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>FC830</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>FC834</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>FC1005; FC1006</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>FC1038; FC1138</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>FC1144</b>			
Drive .....	7540245		6859
Transaxle .....	7540243		6846
<b>FC1660</b>			
Gen. ....	7540169		3V355
P.T.O. ....	7540165		6834
<b>K3904</b>			
Drive .....	7540164	2630	6863
<b>K3909</b>			
Blade .....	7540105		6830
Trans. ....	7540111	2450	6845
<b>K3954</b>			
Drive .....	7540164	2630	6863
<b>K4024</b>			
Blade .....	7540188		6951
Drive .....	7540136		6931
<b>K4150</b>			
Blade .....	7540147	3520	6952
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>K4200</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>K4204</b>			
Belt .....	7540127		6966
<b>K4300; K4304</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>K4600</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>K4604</b>			
Blade .....	7540118		6963
Trans.; W/52" Belt O.C. ....	7540147	3520	6952
Trans.; W/59" Belt O.C. ....	7540937	3590	6959
<b>K4700</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>K4704</b>			
Belt .....	7540127		6966
<b>K6698</b>			
Blade .....	7540112	3800	6980
Trans. ....	7540113	3480	6948
<b>K9604</b>			
P.T.O. ....	7540165		6834
<b>MS3-412</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>MS6-650; MS6-660</b>			
Trans. ....	7540112	3800	6980
<b>MS380</b>			
Blade .....	7540138	3500	6950
<b>MTD7111A68; MTD7114A68</b>			
Deck .....	7540145A		6488BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>P3605</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>P4355</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>R3605; R3606; R3607</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>R4355; R4356</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>R4978; R4979</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>R4997</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>R5258</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>R8109</b>			
Drive .....	7540245		6859
Transaxle .....	7540243		6846
<b>TMO33907B</b>			
Deck .....	7540145A		6488BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR
<b>TMO33909B</b>			
Deck .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>TMO33918A</b>			
Deck .....	7540145A		6488BR
Trans. ....	7540266		6775BR
<b>TMO-339612; TMO-3100002</b>			
Eng. To Deck .....	7540371A		6402BR
<b>TMO-3101805</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>TMO-3103203; TMO-3104204</b>			
Eng. To Deck .....	7540371A		6402BR
<b>TMO-3204205</b>			
Eng. To Deck .....	7540371A		6402BR
Trans. ....	7540441		6417BR
<b>TMO-3204601</b>			
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>TMO-3250008</b>			
Eng. To Deck .....	7540371A		6402BR
<b>TMO-3304602</b>			
Cross Deck .....	7540349		6637BR
<b>TMO-3399006</b>			
Eng. To V.S. ....	7540358		6419BR
<b>TMO-3400005; TMO-3500006</b>			
Trans. ....	7540441		6417BR
<b>TMO-3510003; TMO-3600007</b>			
Eng. To Deck .....	7540439		6406BR
<b>Z4205</b>			
Eng. To Variator .....	7540135		6925
Variator To Trans. ....	7540136		6931
<b>Z4655</b>			
Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>Z4655 - Continued</b>			
Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>Z7605</b>			
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>Z9605</b>			
P.T.O. ....	7540165		6834
Trans. ....	7540124	2570	6857
<b>MURRAY</b>			
<b>0-2503; 0-2512; 0-2513; 0-2523; 0-3013; 0-3033</b>			
Blade .....	37X36		6855
Trans. ....	37X6		6837
<b>0-3213; 0-3223; 0-3233</b>			
Blade .....	37X8		6862
Trans.; W/37" Belt O.C. ....	37X6		6837
Trans.; W/44" Belt O.C. ....	37X9		6844
<b>0-3656; 0-3666; 0-3667; 0-3687; 0-3697</b>			
Cross Deck .....			6846
Eng. To Deck .....	21649		6449BR
Trans. ....	21615		6895
<b>0-4166</b>			
Deck .....	23749		6899
Right Angle Drive .....	23853		A41
Trans. ....	23098		6793BR
<b>0-4169</b>			
Right Angle Drive .....	23072		6843
Trans. ....	23098		6793BR
<b>0-4266</b>			
Blade .....	23748		6862
Cross Drive .....	23749		6899
Trans. ....	23098		6793BR
<b>1-2503; 1-2513</b>			
Blade .....	37X36		6855
Trans. ....	20716		6837
<b>1-3013; 1-3033</b>			
Blade .....	37X2		6848
Trans.; W/37" Belt O.C. ....	37X6		6837
Trans.; W/41" Belt O.C. ....	20555		6841
<b>1-3213; 1-3233</b>			
Blade .....	37X8		6862
Trans.; W/37" Belt O.C. ....	21706		6837
Trans.; W/44" Belt O.C. ....	37X9		6844
<b>1-3613; 1-3633</b>			
Blade .....	20558		6864
Trans. ....	37X6		6837
<b>1-25010; 1-25030; 1-25130</b>			
Blade .....	37X36		6855
Trans. ....	20716		6837
<b>1-30150</b>			
Blade .....	21649		6449BR
Trans. ....	37X6		6837
<b>1-30334</b>			
Blade .....	37X34		6877
Drive .....	37X27		6434BR
<b>1-30350</b>			
Blade .....	21649		6449BR
Trans. ....	37X6		6837
<b>1-36334</b>			
Blade .....	37X27		6434BR
Drive .....	37X27		6434BR
<b>1-36336; 1-36337</b>			
Blade .....	37X27		6434BR
<b>1-36358</b>			
Blade .....	37X27		6434BR
Drive .....	37X35		6713BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>1-36670; 1-36970</b>			
Blade; W/55" Belt O.C. ....	37X12		6449BR
Blade; W/59" Belt O.C. ....	37X24		6859
Cross Drive .....	37X3		6846
Drive .....	37X11		6452BR
<b>1-41660</b>			
Drive .....	37X15		6862
Right Angle Drive .....	37X23		6843
<b>1-41690</b>			
Eng. To J.S. ....	37X15		6862
Trans. ....	37X14		6843
<b>1-42000</b>			
Cross Drive .....	37X22		6642BR
<b>1-42660</b>			
Trans.; W/43" Belt O.C. ....	37X23		6843
Trans.; W/62" Belt O.C. ....	37X15		6862
Trans.; W/99" Belt O.C. ....	37X22		6642BR
<b>1-43660</b>			
Cross Drive .....	37X22		6642BR
Deck .....	37X34		6877
<b>2-2513</b>			
Blade .....	37X36		6855
Trans. ....	20716		6837
<b>2-3013; 2-3043</b>			
Blade .....	37X2		6848
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/41" Belt O.C. ....	37X1		6841
<b>2-3052</b>			
Trans. ....	37X38		6425BR
<b>2-3063</b>			
Blade .....	37X2		6848
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/41" Belt O.C. ....	37X1		6841
<b>2-3233</b>			
Blade .....	21058		6863
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/44" Belt O.C. ....	21059		6844
<b>2-5517X10A</b>			
Blade .....	37X12		6449BR
Trans. ....	37X65		6453BR
<b>2-6503</b>			
Blade .....	37X39		6601BR
Deck .....	37X27		6434BR
Trans. ....	37X35		6713BR
<b>2-6504</b>			
Blade .....	37X39		6601BR
Deck .....	37X27		6434BR
<b>2-2402</b>			
Blade .....	37X21		6451BR
<b>2-25020; 2-25130</b>			
Blade .....	37X36		6855
Trans. ....	20716		6837
<b>2-25501; 2-25502</b>			
Blade; W/50" Belt O.C. ....	37X37		6850
Blade; W/55" Belt O.C. ....	37X36		6855
Trans. ....	37X38		6425BR
<b>2-31501</b>			
Deck .....	37X34		6877
Drive .....	37X27		6434BR
<b>2-36503; 2-36504; 2-36510</b>			
Blade .....	37X39		6601BR
Drive .....	37X35		6713BR
<b>2-39003; 2-39004</b>			
Blade .....	37X21		6451BR
<b>3-0502; 3-0533</b>			
Eng. To Deck .....	37X57		6498BR
Trans. ....	37X38		6425BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>3-2503; 3-2513</b>			
Blade .....	37X36		6855
Trans. ....	20716		6837
<b>3-3013; 3-3043; 3-3063</b>			
Blade .....	37X2		6848
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/41" Belt O.C. ....	37X1		6841
<b>3-3233</b>			
Blade; W/44" Belt O.C. ....	21059		6844
Blade; W/63" Belt O.C. ....	21058		6863
Deck .....	21508		6863
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/44" Belt O.C. ....	21059		6844
<b>3-3502</b>			
Blade .....	37X37		6850
Trans.; W/40" Belt O.C. ....	37X38		6425BR
Trans.; W/55" Belt O.C. ....	37X36		6855
<b>3-3633</b>			
Blade .....	20558		6864
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/46" Belt O.C. ....			6846
<b>3-3666</b>			
Blade .....			6846
Deck .....	21649		6449BR
Trans. ....	21615		6895
<b>3-6509</b>			
Drive .....	37X31		6893
<b>3-24012</b>			
Deck .....	37X37		6850
Trans. ....	37X38		6425BR
<b>3-25501; 3-25502</b>			
Blade .....	37X36		6855
Traction .....	37X38		6425BR
<b>3-30501; 3-30502; 3-30507; 3-30702</b>			
Deck .....	37X37		6850
Trans. ....	37X38		6425BR
<b>3-31704</b>			
Blade .....	37X34		6877
Drive; W/50" Belt O.C. ....	37X37		6850
Drive; W/83" Belt O.C. ....	37X27		6434BR
<b>3-36202</b>			
Blade; W/46" Belt O.C. ....	37X3		6846
Blade; W/59" Belt O.C. ....	37X24		6859
Drive .....	37X11		6452BR
Eng. To Deck .....	37X24		6859
Trans. ....	37X11		6452BR
<b>3-36506</b>			
Transaxle .....	37X45		6490BR
<b>3-36508</b>			
Blade; W/Kevlar Belt .....	37X27		6434BR
Blade; W/O Kevlar Belt .....	37X39		6601BR
Drive .....	37X35		6713BR
Transaxle .....	37X45		6490BR
<b>3-36509</b>			
Blade .....	37X27		6434BR
Drive .....	37X35		6713BR
<b>3-36523</b>			
Blade .....	37X39		6601BR
<b>3-36528</b>			
Transaxle .....	37X45		6490BR
<b>3-325501; 3-325502</b>			
Blade .....	37X36		6855
Traction .....	37X38		6425BR
<b>4-2503; 4-2513</b>			
Blade; W/55" Belt O.C. ....	37X36		6855
Blade; W/56" Belt O.C. ....	20717		6856
Trans. ....	20716		6837

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>4-3013; 4-3033; 4-3043; 4-3063</b>			
Blade; W/41" Belt O.C. ....	20555		6841
Blade; W/48" Belt O.C. ....	37X2		6848
Deck .....	20556		6848
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/41" Belt O.C. ....	37X1		6841
<b>4-3233</b>			
Blade .....	21058		6863
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/44" Belt O.C. ....	21059		6844
<b>4-3273; 4-3293</b>			
Blade .....	21049		6855
Trans.; W/44" Belt O.C. ....	21059		6844
Trans.; W/85" Belt O.C. ....	21614		6885
<b>4-3673; 4-3693</b>			
Blade .....	21649		6449BR
Trans.; W/46" Belt O.C. ....			6846
Trans.; W/85" Belt O.C. ....	21614		6885
<b>4-3696; 4-3697</b>			
Blade .....	37X3		6846
Cross Drive .....	37X3		6846
Deck .....	37X12		6449BR
Trans. ....	37X11		6452BR
<b>4-24036</b>			
Blade .....	37X24		6859
Cross Drive .....	37X3		6846
<b>4-24042</b>			
Blade; W/11 H.P. Eng. ....	37X21		6451BR
Blade; W/16, 18 H.P. Eng. ....	37X40		6451BR
Cross Drive .....	37X22		6642BR
<b>4-25501</b>			
Deck .....	37X36		6855
<b>4-30501; 4-30502; 4-30702</b>			
Blade .....	37X50		6854
Trans. ....	37X38		6425BR
<b>4-31704</b>			
Blade .....	37X34		6877
Drive .....	37X27		6434BR
<b>4-36202</b>			
Blade .....	37X24		6859
Cross Drive .....	37X3		6846
Eng. To J.S. ....	23882		A57
Trans. ....	37X11		6452BR
<b>4-36506</b>			
Deck .....	37X27		6434BR
Trans. ....	37X35		6713BR
<b>4-36508</b>			
Trans. ....	37X35		6713BR
<b>4-39003; 4-39004</b>			
Blade .....	37X40		6451BR
Cross Drive .....	37X22		6642BR
<b>4-40700</b>			
Transaxle .....	37X45		6490BR
<b>4-42204</b>			
Drive .....	37X11		6452BR
<b>5-2503; 5-2513; 5-2519</b>			
Blade; W/37" Belt O.C. ....	20716		6837
Blade; W/56" Belt O.C. ....	20717		6856
<b>5-3013; 5-3033; 5-3043; 5-3063</b>			
Blade; W/41" Belt O.C. ....	20555		6841
Blade; W/48" Belt O.C. ....	37X2		6848
Deck .....	20556		6848
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/41" Belt O.C. ....	37X1		6841
<b>5-3233</b>			
Blade; W/46" Belt O.C. ....	37X3		6846
Blade; W/63" Belt O.C. ....	21058		6863
Deck .....	37X12		6449BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>5-3233 - Continued</b>			
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/44" Belt O.C. ....	21059		6844
Trans.; W/95" Belt O.C. ....	37X11		6452BR
<b>5-3643</b>			
Blade; W/46" Belt O.C. ....			6846
Blade; W/55" Belt O.C. ....	37X12		6449BR
Cross Drive .....	37X3		6846
Deck .....	21649		6449BR
Drive .....	37X10		6885
Trans. ....	21614		6885
<b>5-3663</b>			
Blade .....	37X12		6449BR
Cross Drive .....	37X3		6846
Drive .....	37X10		6885
<b>5-3666</b>			
Blade .....	37X12		6449BR
Cross Drive .....	37X3		6846
Deck .....	37X12		6449BR
Transaxle .....	37X11		6452BR
<b>5-3667; 5-3696; 5-3697</b>			
Blade .....			6846
Cross Drive .....	37X3		6846
Deck .....	37X12		6449BR
Transaxle .....	37X11		6452BR
<b>5-25501</b>			
Blade .....	37X12		6449BR
Traction .....	37X38		6425BR
<b>5-25502</b>			
Blade .....	37X50		6854
Traction .....	37X38		6425BR
<b>5-30502</b>			
Trans. ....	37X38		6425BR
<b>5-30702; 5-30705</b>			
Blade .....	37X50		6854
Traction; W/40" Belt O.C. ....	37X38		6425BR
Traction; W/50" Belt O.C. ....	37X37		6850
<b>5-31704</b>			
Blade .....	37X24		6859
Deck .....	37X34		6877
Drive .....	37X27		6434BR
<b>5-36506</b>			
Blade .....	37X43		6601BR
Deck .....	37X43		6601BR
Drive .....	37X55		6891
<b>5-36508</b>			
Deck .....	37X43		6601BR
Drive .....	37X55		6891
<b>5-36508X4</b>			
Blade .....	37X43		6601BR
Deck .....	37X43		6601BR
Drive .....	37X55		6891
<b>5-36523</b>			
Drive .....	37X55		6891
Eng. To Deck .....	37X43		6601BR
<b>5-36528</b>			
Eng. To Deck .....	37X43		6601BR
<b>5-38205; 5-38206</b>			
Blade .....	37X40		6451BR
Cross Drive .....	37X22		6642BR
Deck .....	37X22		6642BR
Drive .....	37X11		6452BR
<b>5-39004</b>			
Blade .....	37X40		6451BR
Cross Drive .....	37X22		6642BR
Deck .....	37X22		6642BR
Eng. To Trans. ....	37X11		6452BR
<b>5-40700; 5-40701</b>			
Blade .....	37X40		6451BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>5-40700; 5-40701 - Continued</b>			
Deck .....	37X40		6451BR
<b>6-2503; 6-2513</b>			
Blade; W/37" Belt O.C. ....	20716		6837
Blade; W/56" Belt O.C. ....	20717		6856
Trans. ....	20716		6837
<b>6-3013; 6-3033; 6-3043; 6-3063</b>			
Blade .....	37X2		6848
Deck .....	20556		6848
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/41" Belt O.C. ....	20555		6841
<b>6-3233</b>			
Blade; W/44" Belt O.C. ....	21059		6844
Blade; W/63" Belt O.C. ....	21058		6863
Deck .....	21058		6863
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/44" Belt O.C. ....	21059		6844
<b>6-3643; 6-3663</b>			
Blade; W/46" Belt O.C. ....			6846
Blade; W/55" Belt O.C. ....	37X12		6449BR
Cross Drive .....	37X3		6846
Deck .....	21649		6449BR
Drive .....	37X10		6885
Trans. ....	21614		6885
<b>6-3666; 6-3667</b>			
Blade; W/46" Belt O.C. ....			6846
Blade; W/55" Belt O.C. ....	37X12		6449BR
Cross Drive .....	37X3		6846
Deck .....	21649		6449BR
Trans. ....	21615		6895
Transaxle .....	37X11		6452BR
<b>6-3696</b>			
Blade .....	37X12		6449BR
Cross Drive .....	37X3		6846
Deck .....	37X12		6449BR
Transaxle .....	37X11		6452BR
<b>6-3697</b>			
Blade; W/46" Belt O.C. ....			6846
Blade; W/55" Belt O.C. ....	37X12		6449BR
Cross Drive .....	37X3		6846
Deck .....	21649		6449BR
Trans. ....	21615		6895
Transaxle .....	37X11		6452BR
<b>6-22501</b>			
Deck .....	37X12		6449BR
Trans. ....	37X38		6425BR
<b>6-25501</b>			
Blade .....	37X12		6449BR
Traction .....	37X38		6425BR
<b>6-25502</b>			
Blade .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>6-030502</b>			
Deck .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>6-30502X4</b>			
Blade .....	37X57		6498BR
Deck .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>6-30526X</b>			
Blade .....	37X51		6376
<b>6-30702; 6-30702X4</b>			
Blade .....	37X57		6498BR
Deck .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>6-30704</b>			
Eng. To Deck .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>6-30705</b>			
Blade .....	37X57		6498BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>6-30705 - Continued</b>			
Deck .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>6-31704</b>			
Blade .....	37X34		6877
Deck .....	37X34		6877
Trans. ....	37X27		6434BR
<b>6-36506</b>			
Deck .....	37X43		6601BR
<b>6-36508</b>			
Deck .....	37X43		6601BR
Eng. To Trans. ....	37X45		6490BR
<b>6-36508X4</b>			
Blade .....	37X43		6601BR
Deck .....	37X43		6601BR
Trans. ....	37X55		6891
<b>6-36534</b>			
Eng. To Deck .....	37X43		6601BR
<b>6-38205; 6-38211</b>			
Cross Drive .....	37X22		6642BR
Deck .....	37X22		6642BR
Eng. To Deck .....	37X40		6451BR
Trans. ....	37X11		6452BR
<b>6-39004</b>			
Blade .....	37X40		6451BR
Cross Drive .....	37X22		6642BR
Deck .....	37X22		6642BR
Eng. To Deck .....	37X40		6451BR
Eng. To Trans. ....	37X26		6463BR
<b>7-2503; 7-2513</b>			
Blade; W/37" Belt O.C. ....	20716		6837
Blade; W/56" Belt O.C. ....	20717		6856
Trans. ....	20716		6837
<b>7-3013; 7-3033</b>			
Blade; W/41" Belt O.C. ....	20555		6841
Blade; W/48" Belt O.C. ....	37X2		6848
Deck .....	20556		6848
Trans.; W/37" Belt O.C. ....	20716		6837
Trans.; W/41" Belt O.C. ....	37X1		6841
<b>7-3643</b>			
Blade .....	37X12		6449BR
Cross Drive .....	37X3		6846
Drive .....	37X10		6885
<b>7-3666; 7-3667; 7-3697</b>			
Blade .....	37X12		6449BR
Cross Drive .....	37X3		6846
Deck .....	37X12		6449BR
Transaxle .....	37X11		6452BR
<b>7-4297</b>			
Blade .....	23214		6859
Cross Drive .....	23223		6895
Drive .....	37X11		6452BR
<b>7-25501</b>			
Deck .....	37X12		6449BR
Trans. ....	37X38		6425BR
<b>7-30502; 7-30502X92</b>			
Deck .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>7-31515</b>			
Deck .....	37X27		6434BR
Drive .....	37X27		6434BR
Trans. ....	37X59		6672BR
<b>7-35500</b>			
Drive .....	37X38		6425BR
<b>7-36506</b>			
Deck .....	37X43		6601BR
<b>7-36508</b>			
Blade .....	37X43		6601BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>7-36508 - Continued</b>			
Deck .....	37X43		6601BR
Drive .....	37X45		6490BR
<b>7-36557</b>			
Blade .....	37X43		6601BR
<b>7-36560</b>			
Blade .....	37X43		6601BR
Deck .....	37X43		6601BR
Drive .....	37X45		6490BR
<b>7-38211; 7-38219; 7-38222</b>			
Cross Drive .....	37X22		6642BR
Deck .....	37X40		6451BR
Trans. ....	37X11		6452BR
<b>7-39004</b>			
Cross Drive .....	37X22		6642BR
Deck .....	37X40		6451BR
Drive .....	37X40		6451BR
Trans. ....	37X26		6463BR
<b>7-40713</b>			
Deck .....	37X40		6451BR
Drive .....	37X40		6451BR
Variator To Trans. ....	37X48		6873
<b>8-21X15; 8-21X22</b>			
Belt; W/30" Deck .....	37X40		6451BR
Cross Drive .....	37X22		6642BR
Trans. ....	37X11		6452BR
<b>8-365X27</b>			
Blade .....	37X43		6601BR
Trans. ....	37X55		6891
<b>8-366X31</b>			
Blade .....	37X43		6601BR
Trans. ....	37X45		6490BR
<b>8-2503; 8-2513; 8-2523</b>			
Blade; W/37" Belt O.C. ....	20716		6837
Blade; W/56" Belt O.C. ....	20717		6856
Trans. ....	20716		6837
<b>8-3013; 8-3033</b>			
Trans. ....	20716		6837
<b>8-3643</b>			
Cross Drive .....	37X3		6846
Deck .....	37X12		6449BR
Drive .....	23347		6882
Trans. ....	37X18		6882
<b>8-3662; 8-3666; 8-3667; 8-3697</b>			
Cross Drive .....	37X3		6846
Deck .....	37X12		6449BR
Drive .....	37X11		6452BR
Trans. ....	37X5		6837
<b>8-4169</b>			
Drive .....	23098		6793BR
Right Angle Drive .....	23072		6843
<b>8-4169X58</b>			
Drive .....	37X40		6451BR
<b>8-4297</b>			
Cross Drive .....	23749		6899
Drive .....	37X11		6452BR
<b>8-6506; 8-6508</b>			
Blade .....	37X43		6601BR
Trans. ....	37X45		6490BR
<b>8-24560</b>			
Belt; W/30" Deck .....	37X40		6451BR
Cross Drive .....	37X22		6642BR
Snow Thrower Attachment; W/43" Belt O.C. ....	11483		6943
Snow Thrower Attachment; W/76" Belt O.C. ....			6876
<b>8-25500</b>			
Drive .....	37X38		6425BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>8-25501; 8-25557</b>			
Blade .....	37X12		6449BR
Traction .....	37X38		6425BR
<b>8-30502</b>			
Drive .....	37X38		6425BR
Eng. To Deck .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>8-30502X5</b>			
Blade .....	37X57		6498BR
Traction .....	37X38		6425BR
<b>8-30532X34</b>			
Eng. To Deck .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>8-31518</b>			
Traction .....	37X29		6739
<b>8-31583</b>			
Blade .....	37X59		6672BR
Drive .....	37X27		6434BR
<b>8-35500</b>			
Drive .....	37X38		6425BR
<b>8-36506</b>			
Blade .....	37X43		6601BR
Drive .....	37X55		6891
<b>8-36506X</b>			
Blade .....	37X43		6601BR
Trans. ....	37X55		6891
<b>8-36508</b>			
Blade .....	37X43		6601BR
Drive .....	37X55		6891
<b>8-36557</b>			
Blade .....	37X43		6601BR
Drive .....	37X43		6601BR
<b>8-36561X; 8-36563X</b>			
Blade .....	37X43		6601BR
Trans. ....	37X45		6490BR
<b>8-36566</b>			
Blade .....	37X43		6601BR
Drive .....	37X43		6601BR
Trans. ....	37X45		6490BR
<b>8-36566X31</b>			
Eng. To Deck .....	37X43		6601BR
<b>8-36568</b>			
Blade .....	37X43		6601BR
Trans. ....	37X45		6490BR
<b>8-36569X34; 8-36570X34</b>			
Blade .....	37X43		6601BR
Drive .....	37X55		6891
<b>8-38208X17</b>			
Blade .....	37X40		6451BR
<b>8-38211; 8-38219</b>			
Cross Drive .....	37X22		6642BR
Deck .....	37X40		6451BR
Trans. ....	37X11		6452BR
<b>8-38222</b>			
Cross Drive .....	37X11		6452BR
Deck .....	37X22		6642BR
Drive .....	37X11		6452BR
<b>8-38222X27</b>			
Belt; W/30" Deck .....	37X40		6451BR
<b>8-39004</b>			
Blade .....	37X40		6451BR
Cross Drive; W/47" Belt O.C. ....	37X66		6475BR
Cross Drive; W/95" Belt O.C. ....	37X11		6452BR
Deck .....	37X22		6642BR
Drive; W/42" Deck; W/4-Speed Drive .....	37X26		6463BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>8-40713</b>			
Deck .....	37X40		6451BR
<b>8-40715; 8-40719X</b>			
Deck .....	37X40		6451BR
Trans. ....	37X45		6490BR
<b>9-2501</b>			
Blade .....	20717		6856
Trans. ....	20715		6837
<b>9-2502; 9-2503; 9-2504; 9-2513; 9-2523</b>			
Blade; W/37" Belt O.C. ....	20716		6837
Blade; W/56" Belt O.C. ....	20717		6856
Trans. ....	20716		6837
<b>9-3013; 9-3033</b>			
Blade .....	37X12		6449BR
Transaxle .....	37X6		6837
<b>9-3653</b>			
Blade .....	21649		6449BR
Cross Drive .....	37X3		6846
Drive .....	23347		6882
<b>9-3662; 9-3666; 9-3667; 9-3697</b>			
Blade .....	21649		6449BR
Cross Drive .....	37X3		6846
Drive .....	37X11		6452BR
<b>9-4166</b>			
Drive .....	23098		6793BR
Right Angle Drive .....	23853		A41
<b>9-4169</b>			
Drive .....	23098		6793BR
Right Angle Drive .....	23072		6843
<b>9-4297</b>			
Cross Drive .....	23749		6899
Drive .....	37X11		6452BR
<b>9-24838</b>			
Blade .....	37X57		6498BR
Traction .....	37X38		6425BR
<b>9-25501</b>			
Blade .....	37X12		6449BR
Drive .....	37X38		6425BR
Traction .....	37X38		6425BR
<b>9-25501C; 9-25502</b>			
Blade .....	37X12		6449BR
Drive .....	37X38		6425BR
<b>9-30502</b>			
Eng. To Deck .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>9-30502C; 9-30502D</b>			
Blade .....	37X57		6498BR
Drive .....	37X38		6425BR
<b>9-30532</b>			
Eng. To Deck .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>9-30533</b>			
Blade .....	37X57		6498BR
Drive .....	37X38		6425BR
Eng. To Deck .....	37X57		6498BR
Traction .....	37X38		6425BR
Trans. ....	37X38		6425BR
<b>9-30553</b>			
Blade .....	37X57		6498BR
<b>9-35500</b>			
Blade .....	37X38		6425BR
Drive .....	37X38		6425BR
<b>9-36600</b>			
Drive .....	37X61		6452BR
Traction .....	37X61		6452BR
<b>9-38211; 9-38219</b>			
Cross Drive .....	37X22		6642BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>9-38211; 9-38219 - Continued</b>			
Deck .....	37X40		6451BR
Drive .....	37X11		6452BR
<b>9-38600; 9-38601; 9-38602; 9-38608; 9-38620</b>			
Traction .....	37X61		6452BR
<b>9-40622</b>			
Deck .....	37X62		6400BR
Trans. ....	37X61		6452BR
<b>9-305029</b>			
Blade .....	37X57		6498BR
Drive .....	37X38		6425BR
<b>28-5250</b>			
Deck .....	37X62		6400BR
<b>44-20014</b>			
Motion Drive .....	37X65		6453BR
<b>44-20032</b>			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X75		6407BR
<b>44-20040</b>			
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
<b>44-20163</b>			
Deck .....	300680		6555BR
Drive .....	57214		6775BR
<b>44-20236</b>			
Motion Drive .....	37X61		6452BR
<b>44-20252</b>			
Deck .....	58170		6675BR
<b>44-20553</b>			
Deck .....	300680		6555BR
Drive .....	326932		6876
<b>81-25010</b>			
Blade .....	37X7		6856
Trans. ....	37X5		6837
<b>81-25030</b>			
Blade .....	37X7		6856
Trans. ....	37X6		6837
<b>81-25130</b>			
Blade .....	37X7		6856
<b>81-30150</b>			
Blade .....	37X12		6449BR
Trans. ....	37X5		6837
<b>81-30334</b>			
Blade; W/30" Deck .....	37X34		6877
Blade; W/36" Deck .....	37X39		6601BR
Drive .....	37X27		6434BR
<b>81-30336; 81-30337; 81-30338</b>			
Blade; W/30" Deck .....	37X34		6877
Blade; W/36" Deck .....	37X39		6601BR
<b>81-30350</b>			
Blade .....	37X12		6449BR
Trans. ....	37X5		6837
<b>81-36334</b>			
Drive .....	37X27		6434BR
<b>81-36336; 81-36337</b>			
Blade .....	37X27		6434BR
Drive .....	37X31		6893
Trans. ....	37X31		6893
<b>81-36358</b>			
Drive .....	37X35		6713BR
<b>81-36670; 81-36970</b>			
Cross Drive .....	37X3		6846
Deck; W/55" Belt O.C. ....	37X12		6449BR
Deck; W/58 1/2" Belt O.C. ....	37X24		6859
Trans. ....	37X11		6452BR

Lawn & Garden Equipment





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
81-40690			
Trans .....	37X26		6463BR
81-41660			
Drive .....	37X15	6862	
Right Angle Drive .....	37X23	6843	
Trans .....	37X15	6862	
81-42000; 81-42600			
Blade .....	37X21	6451BR	
Cross Deck .....	37X22	6642BR	
81-42660			
Drive .....	37X15	6862	
81-43660			
Blade .....	37X21	6451BR	
Cross Drive .....	37X22	6642BR	
Trans .....	37X26	6463BR	
81-363334			
Blade .....	37X27	6434BR	
Trans .....	37X27	6434BR	
82-42660			
Right Angle Drive .....	37X23	6843	
Trans .....	37X15	6862	
93-6052-0			
Deck .....	37X12	6449BR	
Motion Drive .....	37X65	6453BR	
93-6084-3; 93-6107-2; 93-6115-5			
Motion Drive .....	37X65	6453BR	
93-7117-0			
Deck .....	300680	6555BR	
Drive .....	57214	6775BR	
822-096			
Motion Drive .....	37X65	6453BR	
822-111			
Cross Deck .....	37X66	6475BR	
Deck; Model No. 46620X15C .....	37X70	6603BR	
Drive .....	37X61	6452BR	
822-114			
Deck .....	37X63	6601BR	
Drive .....	37X61	6452BR	
822-144			
Motion Drive .....	37X81	6690BR	
850-484C			
Deck .....	300680	6555BR	
Drive .....	54758	6551BR	
850-0530			
Motion Drive .....	37X61	6452BR	
Mower Drive .....	37X62	6400BR	
850-5778			
Motion Drive .....	37X65	6453BR	
850-6156			
Motion Drive .....	37X61	6452BR	
Mower Drive .....	37X62	6400BR	
1905			
Blade; W/37" Belt O.C. ....	20716	6837	
Blade; W/56" Belt O.C. ....	20717	6856	
3053X1B			
Deck .....	37X57	6498BR	
Trans .....	37X65	6453BR	
3055A			
Blade .....	37X57	6498BR	
Trans .....	37X65	6453BR	
3055X92A			
Deck .....	37X57	6498BR	
Eng. To Trans. ....	37X65	6453BR	
3202-15; 3402-05; 3402-15			
Deck .....	48044	6454BR	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
3666; 3667			
Blade; W/46" Belt O.C. ....			6846
Blade; W/55" Belt O.C. ....	21649		6449BR
Blade; W/56" Belt O.C. ....	20717		6856
Trans. ....	21615		6895
3697			
Blade .....			6846
Blade To Deck .....	21649		6449BR
Cross Drive .....	20555		6841
Deck .....	21649		6449BR
Trans. ....	21615		6895
4060AX8A; 4060X8B			
Deck .....	37X62		6400BR
Drive .....	37X61		6452BR
8880			
Motion Drive .....	37X61		6452BR
8880A; 8880B			
Cross Deck .....	37X66		6475BR
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
8897C			
Deck .....	300680		6555BR
Drive .....	54758		6551BR
8906			
Motion Drive .....	37X65		6453BR
8917			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X62		6400BR
8921			
Cross Deck .....	37X66		6475BR
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
8940			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X62		6400BR
25500X92A			
Deck .....	37X12		6449BR
Motion Drive .....	37X65		6453BR
25511X1A			
Deck .....	37X12		6449BR
Eng. To Trans. ....	37X65		6453BR
25511X1B			
Deck .....	37X12		6449BR
Motion Drive .....	37X65		6453BR
25511X1C; 25511X1C1			
Deck .....	37X12		6449BR
Trans. ....	37X65		6453BR
25511X1D; 25511X1E			
Deck .....	37X12		6449BR
Motion Drive .....	37X65		6453BR
25515A; 25515B			
Deck .....	37X12		6449BR
Trans. ....	37X65		6453BR
25515C; 25517X10A			
Deck .....	37X12		6449BR
Motion Drive .....	37X65		6453BR
30500X92A; 30504X92A; 30505X92A			
Motion Drive .....	37X65		6453BR
30508X34A; 30534X1A; 30535X1A			
Deck .....	37X57		6498BR
Eng. To Trans. ....	37X65		6453BR
30535X1B; 30535X1C; 30535X1D			
Motion Drive .....	37X65		6453BR
30536X1A; 30537X1A			
Deck .....	37X57		6498BR
Eng. To Trans. ....	37X65		6453BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>30538X1A; 30539X1A; 30539X1B</b>			
Motion Drive .....	37X65		6453BR
<b>30540A; 30540X5A</b>			
Deck .....	37X57		6498BR
Eng. To Trans. ....	37X65		6453BR
<b>30540X10A</b>			
Deck .....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>30541A; 30542X58A; 30543X4A; 30544X92A;</b>			
<b>30544X92B; 30544X92C; 30544X92D;</b>			
<b>30544X192A; 30545X92A; 30545X92B</b>			
Motion Drive .....	37X65		6453BR
<b>30545X192A; 30546X4A; 30546X99A;</b>			
<b>30546X199A</b>			
Motion Drive .....	37X65		6453BR
<b>30550A; 30550B</b>			
Deck .....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>30550C; 30550D; 30550E; 30550F; 30550G;</b>			
<b>30550H; 30550X30A; 30550X92A</b>			
Motion Drive .....	37X65		6453BR
<b>30550X92B; 30550X92C</b>			
Deck .....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>30550X92D; 30550X100A; 30550X199A</b>			
Motion Drive .....	37X65		6453BR
<b>30551A</b>			
Deck .....	37X57		6498BR
Eng. To Trans. ....	37X65		6453BR
<b>30551B; 30551D; 30552X12A</b>			
Motion Drive .....	37X65		6453BR
<b>30560A</b>			
Deck .....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>30560B; 30560C; 30560D; 30560E; 30560F</b>			
Motion Drive .....	37X65		6453BR
<b>30560X1A</b>			
Deck .....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>30560X5A; 30560X5B; 30560X5D; 30560X15A</b>			
Motion Drive .....	37X65		6453BR
<b>30560X20</b>			
P.T.O. ....	37X57		6498BR
<b>30560X60A; 30560X60B; 30560X99A; 30562A;</b>			
<b>30562X25A; 30565A</b>			
Motion Drive .....	37X65		6453BR
<b>30570X8A; 30570X8B</b>			
Deck .....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>30570X8C; 30570X8D; 30570X14A; 30572A;</b>			
<b>30572X9A; 30573X10A; 30574X55A; 30575X7A;</b>			
<b>30575X8A; 30575X8B</b>			
Motion Drive .....	37X65		6453BR
<b>30575X8C; 30575X14A; 30575X31A; 30576X10;</b>			
<b>30576X10B; 30576X10C; 30576X10D;</b>			
<b>30577X7A; 30577X8A; 30577X31A</b>			
Motion Drive .....	37X65		6453BR
<b>30577X31B</b>			
Motion Drive .....	37X65		6453BR
<b>30580X34A</b>			
Deck .....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>30580X80A; 30581-1A; 30590X1A; 30591X1A</b>			
Motion Drive .....	37X65		6453BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>30592A</b>			
Blade .....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>30592X1A; 30594X1A; 30594X1B; 30594X1C;</b>			
<b>30595X1A; 30596X1A; 30597X1A; 30597X1B;</b>			
<b>30597X1C; 30598X1A</b>			
Motion Drive .....	37X65		6453BR
<b>30598X1B; 30599X1A</b>			
Motion Drive .....	37X65		6453BR
<b>31602A; 31602B; 31602X5A; 31602X60A;</b>			
<b>31602X60B</b>			
Motion Drive .....	37X61		6452BR
<b>31720X20</b>			
Drive .....	37X61		6452BR
P.T.O. ....	37X74		6674BR
<b>36506</b>			
Eng. To Deck .....	37X43		6601BR
<b>36538X1A</b>			
Deck .....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>36566</b>			
Eng. To Deck .....	37X43		6601BR
<b>36622X1E</b>			
Deck .....	37X12		6449BR
Motion Drive .....	37X65		6453BR
<b>38221A; 38221X27A</b>			
Cross Deck .....	37X22		6642BR
Eng. To Deck .....	37X40		6451BR
Eng. To Trans. ....	37X11		6452BR
<b>38500A; 38500B; 38500X30A; 38500X83A;</b>			
<b>38500X92A; 38500X92B; 38500X192A;</b>			
<b>38500X192B; 38502X51E; 38502X70A</b>			
Mower Drive .....	37X86		6412BR
<b>38502X98D; 38504X25A; 38506X4A;</b>			
<b>38506X199A; 38510X50B; 38514X95A;</b>			
<b>38515X83A; 38515X92A; 38515X92B;</b>			
<b>38516X53B</b>			
Mower Drive .....	37X86		6412BR
<b>38560X81A; 38560X181A</b>			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X86		6412BR
<b>38600A; 38600B; 38600C; 38600D; 38600E;</b>			
<b>38602X5A; 38602X5B; 38602X5C; 38602X5D;</b>			
<b>38602X5E</b>			
Deck .....	37X63		6601BR
Motion Drive .....	37X61		6452BR
<b>38602X95A; 38604A; 38604B; 38608A; 38608B;</b>			
<b>38608C; 38608X12A; 38608X12B; 38608X12C;</b>			
<b>38608X12D</b>			
Deck .....	37X63		6601BR
Motion Drive .....	37X61		6452BR
<b>38608X12E; 38608X12F; 38608X12G;</b>			
<b>38608X12H</b>			
Deck .....	37X63		6601BR
Motion Drive .....	37X61		6452BR
<b>38608X12XC</b>			
Motion Drive .....	37X61		6452BR
<b>38608X92A; 38608X92B; 38608X92C;</b>			
<b>38608X92D; 38609X1A; 38611X60A;</b>			
<b>38611X60B</b>			
Deck .....	37X63		6601BR
Motion Drive .....	37X61		6452BR
<b>38612A</b>			
Motion Drive .....	37X61		6452BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>				<b>MURRAY - Continued</b>			
38612X34A; 38612X34B; 38615A; 38615B; 38616A; 38617X5A; 38617X5B; 38618X92A; 38618X92B; 38618X92C				40508X52A; 40508X92A; 40508X92B; 40508X92C; 40508X92D; 40508X92E; 40508X92G; 40509X92A; 40530X83A; 40530X92A			
Deck ..... 37X63			6601BR	Mower Drive ..... 37X62			6400BR
Motion Drive ..... 37X61			6452BR				
38618X92D; 38618X92E; 38618X192A; 38619X1A; 38619X1B; 38623X5A; 38623X5B; 38623X5C; 38623X5D; 38624X12A				40536X4A; 40538A; 40541A; 40541B; 40541C; 40541D; 40541E; 40541F; 40541X30A; 40541X99A			
Deck ..... 37X63			6601BR	Mower Drive ..... 37X62			6400BR
Motion Drive ..... 37X61			6452BR				
38624X12B; 38624X12C; 38629X1A; 38629X1B; 38629X1C; 38629X1D; 38631X8A; 38631X8B; 38631X14A; 38633X92A				40541X99B; 40541X99C; 40541X99D; 40541X99E; 40542A; 40542B; 40542C; 40542D; 40542E			
Deck ..... 37X63			6601BR	Mower Drive ..... 37X62			6400BR
Motion Drive ..... 37X61			6452BR				
38633X92B; 38633X192A; 38633X192B				40560X50D			
Deck ..... 37X63			6601BR	Motion Drive ..... 37X61			6452BR
Motion Drive ..... 37X61			6452BR	Mower Drive ..... 37X62			6400BR
38692A				40560X50E			
Motion Drive ..... 37X61			6452BR	Mower Drive ..... 37X62			6400BR
38701A; 38701B; 38701C; 38702A; 38702B; 38702C; 38702D; 38702X7A; 38702X7B; 38702X8A				40564X51D			
Deck ..... 37X63			6601BR	Motion Drive ..... 37X61			6452BR
Motion Drive ..... 37X61			6452BR	Mower Drive ..... 37X62			6400BR
38702X8B; 38702X8C; 38702X8D; 38702X8E; 38702X14A				40601A; 40601B; 40601X34A; 40602X5A; 40602X5B; 40602X5C; 40602X5D; 40603A; 40603B; 40603C			
Deck ..... 37X63			6601BR	Deck ..... 37X62			6400BR
Motion Drive ..... 37X61			6452BR	Drive ..... 37X61			6452BR
38702X20				40604A; 40604B; 40604C; 40606X8A; 40606X8B; 40607A; 40607B; 40607X9A; 40608A; 40611X5A			
Motion Drive ..... 37X61			6452BR	Deck ..... 37X62			6400BR
P.T.O. .... 37X65			6453BR	Drive ..... 37X61			6452BR
38702X27A; 38702X27B; 38703X15A; 38705A; 38705X5A; 38705X5B; 38705X30A; 38706X99A; 38706X99B; 38710A				40612X99A; 40612X99B; 40613X80A; 40613X80B; 40614A			
Deck ..... 37X63			6601BR	Deck ..... 37X62			6400BR
Motion Drive ..... 37X61			6452BR	Drive ..... 37X61			6452BR
38710B; 38710X99A; 38713X71A; 38715A; 38715B; 38715X82A; 38716X82A				40614B; 40614C			
Deck ..... 37X63			6601BR	Motion Drive ..... 37X61			6452BR
Motion Drive ..... 37X61			6452BR	Mower Drive ..... 37X62			6400BR
39013A				40619A			
Cross Deck ..... 37X22			6642BR	Deck ..... 37X62			6400BR
Eng. To Deck ..... 37X40			6451BR	Drive ..... 37X61			6452BR
Trans. .... 37X26			6463BR	40620			
39013B; 39013X5A				Drive ..... 37X61			6452BR
Cross Deck ..... 37X22			6642BR	40620A; 40620B; 40620C; 40622X1A; 40622X1B; 40622X1C; 40622X5A; 40622X5B; 40622X5C; 40622X15A			
Drive ..... 37X26			6463BR	Deck ..... 37X62			6400BR
Eng. To Deck ..... 37X40			6451BR	Drive ..... 37X61			6452BR
39562X8A				40622X15B; 40622X15C; 40625A; 40625X5A; 40625X25A; 40627A; 40627B; 40627C; 40627D; 40627E			
Motion Drive ..... 37X65			6453BR	Deck ..... 37X62			6400BR
39700A; 39701A				Drive ..... 37X61			6452BR
Deck ..... 300680			6555BR	40627X92A; 40627X92B; 40627X92C; 40627X92D; 40628X1A; 40628X1B; 40629X1A; 40629X80A; 40631A; 40631X8A			
Drive ..... 54758			6551BR	Deck ..... 37X62			6400BR
40501X30A				Drive ..... 37X61			6452BR
Mower Drive ..... 37X62			6400BR	40634A; 40701X25A; 40702X92A; 40702X92B; 40702X92C; 40702X92E; 40702X92F; 40703X60A; 40703X60B; 40703X60C			
40504X92A				Deck ..... 37X62			6400BR
Deck Drive ..... 37X62			6400BR	Drive ..... 37X61			6452BR
Drive ..... 94608			6633BR	40634A; 40701X25A; 40702X92A; 40702X92B; 40702X92C; 40702X92E; 40702X92F; 40703X60A; 40703X60B; 40703X60C			
40507X8A; 40507X8B; 40507X8C; 40507X31A; 40507X31B				Deck ..... 37X62			6400BR
Drive ..... 94608			6633BR	Drive ..... 37X61			6452BR
Mower Drive ..... 37X62			6400BR	40703X60D			
				Deck ..... 37X62			6400BR
				Drive ..... 37X61			6452BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
40705X99A Drive .....	37X61		6452BR
40705X991 Drive .....	37X62		6400BR
40706A; 40706B; 40707A; 40708A; 40708B; 40708C; 40708X8A; 40708X8B; 40708X20; 40708X30A Deck .....	37X62		6400BR
Drive .....	37X61		6452BR
40708X92A; 40708X92B; 40708X192A; 40708X192B; 40709X6A; 40710A; 40710B; 40712X99A; 40712X199A; 40715X99A Deck .....	37X62		6400BR
Drive .....	37X61		6452BR
40715X99B; 40715X199A; 40715X199B; 40717A; 40808X8A; 40808X8B; 40808X8C; 40808X8D; 40808X14A; 40808X14B Deck .....	37X62		6400BR
Drive .....	37X61		6452BR
40900A; 40900B; 40900X30A; 40901X5A; 40906X6A; 40906X62A Deck .....	37X62		6400BR
Drive .....	37X80		6503BR
40907X20 Deck .....	37X62		6400BR
40910A; 40910B Deck .....	37X62		6400BR
Drive .....	37X61		6452BR
42201A; 42203X5A; 42206X80A; 42207X6A Drive .....	37X81		6690BR
42500A; 42500B; 42500C; 42500D; 42500X30A; 42500X30B; 42500X82A; 42500X82B Deck .....	37X88		6401BR
42500X99A; 42504X71A; 42504X71B; 42504X99A; 42504X99B; 42505X92A; 42506X92A; 42508X92A; 42509X92B; 42510A Mower Drive .....	37X88		6401BR
42511X4A; 42511X4B; 42512X99A; 42514X8A; 42514X31A; 42515X92A; 42515X92B Mower Drive .....	37X88		6401BR
42516X92A Deck .....	37X88		6401BR
42516X92B Deck .....	37X88		6401BR
Drive .....	37X87		6438BR
42517X82A; 42533X30A; 42534A; 42534X18A; 42534X25A; 42534X30A; 42536X92A; 42536X192A; 42537A; 42537X18A Mower Drive .....	37X88		6401BR
42539A; 42539X18A; 42539X92A; 42542X6A; 42543X6A; 42544X8A; 42544X8B; 42544X8C; 42544X8D; 42544X8E Mower Drive .....	37X88		6401BR
42544X8F; 42544X8G; 42544X31A; 42544X99A; 42560X30A Mower Drive .....	37X88		6401BR
42560X83A Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42560X92A Deck .....	37X88		6401BR
Drive .....	37X61		6452BR
42560X92B Mower Drive .....	37X88		6401BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
42560X192A Deck .....	37X88		6401BR
Drive .....	37X61		6452BR
42560X192B Deck .....	37X88		6401BR
42561X8A; 42561X8B Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42567X6A Mower Drive .....	37X88		6401BR
42567X30A Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42569X4A Mower Drive .....	37X88		6401BR
42569X6A; 42570X18A; 42571X8A; 42571X8B Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42571X8C; 42571X8D Mower Drive .....	37X88		6401BR
42571X31A Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42571X31B Mower Drive .....	37X88		6401BR
42572X8A; 42572X31A; 42575X81A; 42576X92A Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42576X92B Mower Drive .....	37X88		6401BR
42576X92C Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42576X92D Mower Drive .....	37X88		6401BR
42578X6A; 42578X30A Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42581X50D Motion Drive .....	37X61		6452BR
42581X95A; 42583A; 42583B; 42583C; 42583X6A Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42583X6B; 42583X6C Mower Drive .....	37X88		6401BR
42583X9A; 42583X30A; 42583X30B; 42583X82A; 42583X82C; 42586X8A; 42586X9A Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42587X50D Motion Drive .....	37X61		6452BR
42590A; 42590B; 42590C Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42590E Mower Drive .....	37X88		6401BR
42590X92A; 42590X92B; 42591X8A; 42591X8B; 42591X31A; 42591X88A; 42591X88B; 42591X92A; 42597X95A; 42598X92A Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
42602A; 42603X60A; 42603X60B; 42614A; 42614X92A; 42621X8A; 42701X5A; 42701X5B; 42702X4A; 42702X99A			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X75		6407BR
42703A; 42704X8A; 42704X8B; 42714X5A; 42718X5A; 42802A; 42802B; 42803X5A; 42812X8A; 42812X8B			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X75		6407BR
42813A; 42813X14A; 42813X92A; 42813X92B; 42814A; 42815X5A; 42815X60A; 42815X60B; 42816A; 42816B			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X75		6407BR
42816C			
Mower Drive .....	37X75		6407BR
42816D; 42817X99A; 42817X99B; 42817X199A; 42819A; 42819B; 42819X5A; 42819X7A; 42819X7B; 42819X8A			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X75		6407BR
42819X8B; 42819X14A; 42819X30A; 42819X62A; 42819X92A; 42820X24A; 42820X30; 42822X60A; 42823A; 42827X99A			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X75		6407BR
42827X99B; 42827X199A; 42827X199B			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X75		6407BR
42828X8A			
Deck .....	37X75		6407BR
Drive .....	37X61		6452BR
42828X8B			
Drive .....	37X61		6452BR
42829A; 42829B; 42830A; 42830B			
Motion Drive .....	37X61		6452BR
42900A; 42904X80A; 42904X80B; 42906X6A; 42906X7A; 42906X8A; 42906X8B; 42906X14A; 42907X8A; 42907X26A			
Deck .....	37X75		6407BR
Drive .....	37X80		6503BR
42907X26B; 42908X6A; 42909A; 42909X60A; 42910A; 42910X30A; 42910X92A; 42910X92B			
Deck .....	37X75		6407BR
Drive .....	37X80		6503BR
42910X92C			
Mower Drive .....	37X75		6407BR
42910X192B			
Deck .....	37X75		6407BR
Drive .....	37X80		6503BR
42910X192C			
Mower Drive .....	37X75		6407BR
42911X65			
P.T.O. ....	37X75		6407BR
42913X5A; 42913X5B; 42915X6A			
Deck .....	37X75		6407BR
Drive .....	37X80		6503BR
42915X30B			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
42915X62A; 42916X7A; 42916X7B; 42916X8A; 42916X8B; 42917X6A; 42917X6B; 42917X6C; 42917X8A; 42918X8A			
Deck .....	37X75		6407BR
Drive .....	37X80		6503BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
42918X8B			
Deck .....	37X75		6407BR
Drive .....	37X80		6503BR
46102X6A; 46102X6B; 46103A; 46103B; 46103X71A; 46103X92A; 46104X8A; 46104X8B; 46104X8C; 46106X89A			
Drive .....	37X68		6636BR
Primary .....	37X96		6418BR
46106X89B; 46107X92A; 46108X89A			
Drive .....	37X68		6636BR
Primary .....	37X96		6418BR
46250A; 46250B; 46250X30A; 46251X6A; 46251X6B; 46253X6A; 46253X6B; 46254X8A; 46254X15A; 46254X15B			
Motion Drive .....	37X81		6690BR
46255X6A; 46256X9A; 46256X109A; 46257X8A; 46257X14A; 46258X6A			
Motion Drive .....	37X81		6690BR
46376X65			
Blade .....	37X66		6475BR
P.T.O. ....	37X69		6508BR
46403X6			
Blade .....	37X66		6475BR
Drive .....	37X69		6508BR
46500X92A; 46501X92A			
Drive .....	37X87		6438BR
Primary .....	37X89		6476BR
Secondary .....	37X66		6475BR
46560X92A; 46560X192A; 46567X6A; 46567X30A; 46568A; 46568X6A; 46569X6A; 46569X6B; 46569X6C; 46569X9A			
Drive .....	37X61		6452BR
Primary .....	37X89		6476BR
Secondary .....	37X66		6475BR
46569X71A; 46569X71B; 46569X82A; 46569X92A; 46570X6A; 46570X6B; 46570X6C; 46570X8A; 46570X8B; 46570X71A			
Drive .....	37X61		6452BR
Primary .....	37X89		6476BR
Secondary .....	37X66		6475BR
46570X71B; 46570X92A; 46573X92A; 46576X92A; 46576X92B; 46577X4A; 46577X6A; 46577X6B; 46577X71A; 46581X92A			
Drive .....	37X61		6452BR
Primary .....	37X89		6476BR
Secondary .....	37X66		6475BR
46581X92B			
Drive .....	37X61		6452BR
Primary .....	37X89		6476BR
Secondary .....	37X66		6475BR
46581X92C			
Drive .....	37X106		6889
Primary .....	37X89		6476BR
Secondary .....	37X66		6475BR
46620A			
Trans. ....	37X66		6475BR
46620B; 46620C			
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
46620X1A			
Drive .....	37X61		6452BR
Secondary .....	37X66		6475BR
46620X5A			
Deck .....	37X70		6603BR
Drive .....	37X31		6893
46620X5B			
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>46620X15A</b>			
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
<b>46620X15B; 46620X15C; 46620X25A</b>			
Cross Deck .....	37X66		6475BR
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
<b>46620X25B</b>			
Cross Deck .....	37X66		6475BR
Drive .....	37X61		6452BR
<b>46621A; 46621B; 46621C; 46621X4A</b>			
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
<b>46621X25A; 46621X92A; 46621X92B;</b>			
<b>46621X92C</b>			
Cross Deck .....	37X66		6475BR
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
<b>46622X9A</b>			
Cross Deck .....	37X63		6601BR
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
<b>46702X99A; 46800A; 46800B; 46800X14A</b>			
Cross Deck .....	37X66		6475BR
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
<b>46801X6A; 46801X62A</b>			
Cross Deck .....	37X66		6475BR
Deck .....	37X70		6603BR
Drive .....	37X80		6503BR
<b>46802X60A; 46803X8A; 46804A</b>			
Cross Deck .....	37X66		6475BR
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
<b>46900A; 46900B</b>			
Cross Deck .....	37X66		6475BR
Deck .....	37X70		6603BR
Drive .....	37X80		6503BR
<b>46901X7A</b>			
Cross Deck .....	37X66		6475BR
Deck .....	37X69		6508BR
Drive .....	37X80		6503BR
<b>46901X92A; 46901X92B; 46901X192A;</b>			
<b>46902X6A; 46902X106A; 46903X60A;</b>			
<b>46904X92A; 46904X192A</b>			
Cross Deck .....	37X66		6475BR
Deck .....	37X70		6603BR
Drive .....	37X80		6503BR
<b>46905X6</b>			
Blade .....	37X66		6475BR
<b>46905X30A; 46906X99A; 46906X199A; 46907A</b>			
Cross Deck .....	37X66		6475BR
Deck .....	37X70		6603BR
Drive .....	37X80		6503BR
<b>48560X92A</b>			
Drive .....	37X61		6452BR
Primary .....	37X93		6492BR
Secondary .....	37X92		6491BR
<b>48560X192A</b>			
Primary .....	37X93		6492BR
Secondary .....	37X92		6491BR
<b>49378X6</b>			
Blade .....	37X66		6475BR
Drive .....	37X69		6508BR
<b>50568X9A</b>			
Drive .....	37X61		6452BR
Primary .....	37X93		6492BR
Secondary .....	37X92		6491BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>52100X92A; 52101X92A</b>			
Primary .....	37X93		6492BR
Secondary .....	37X92		6491BR
<b>52161X89A</b>			
Drive .....	37X97		6432BR
Primary .....	37X93		6492BR
Secondary .....	37X92		6491BR
<b>52161X89B; 52370X92A; 52370X192A;</b>			
<b>52431X92A; 52461X89A</b>			
Primary .....	37X93		6492BR
Secondary .....	37X92		6491BR
<b>68624X12B</b>			
Motion Drive .....	37X61		6452BR
<b>90623; 90624</b>			
Deck .....	37X62		6400BR
Trans. ....	37X61		6452BR
<b>95193</b>			
Blade - Right .....	300142		6741
Deck .....	58170		6675BR
Eng. ....	57214		6775BR
<b>305518</b>			
Deck .....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>309002X24; 309007X8</b>			
Deck Drive .....	37X110		6656BR
<b>405002X8A; 405002X31A; 405014X92A;</b>			
<b>405015X92A; 405015X92B; 405019X50A;</b>			
<b>405618X81A</b>			
Mower Drive .....	37X62		6400BR
<b>425003X8A; 425003X31A; 425003X71A;</b>			
<b>425007X92B; 425008X8A; 425008X31A;</b>			
<b>425009X8A; 425009X31A</b>			
Deck .....	37X88		6401BR
<b>425303X92A; 425303X92B</b>			
Motion Drive .....	37X112		6682BR
Mower Drive .....	37X88		6401BR
<b>425306X48A; 425307X24A</b>			
Motion Drive .....	37X112		6682BR
<b>425610X99A</b>			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
<b>425610X99B</b>			
Mower Drive .....	37X88		6401BR
<b>425611X99A</b>			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X88		6401BR
<b>425611X99B; 425611X99C; 425612X99A;</b>			
<b>425613X8A; 425613X31A; 425614A;</b>			
<b>425614X92A</b>			
Mower Drive .....	37X88		6401BR
<b>461000X71A; 461007X92A; 461007X92B;</b>			
<b>461018X99A; 461018X99B</b>			
Drive .....	37X68		6636BR
Primary .....	37X96		6418BR
<b>465306X8A; 465306X8B</b>			
Motion Drive .....	37X112		6682BR
<b>465600X71A; 465602X31A</b>			
Drive .....	37X106		6889
Primary .....	37X89		6476BR
Secondary .....	37X66		6475BR
<b>465612X99A</b>			
Drive .....	37X61		6452BR
Primary .....	37X89		6476BR
Secondary .....	37X66		6475BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>465612X99B; 465616X6A; 465619X71A; 465620X71A</b>			
Drive .....	37X106		6889
Primary .....	37X89		6476BR
Secondary .....	37X66		6475BR
<b>503663</b>			
Blade .....			6846
Deck .....	21649		6449BR
Trans. ....	21614		6885
<b>521000X71A</b>			
Primary .....	37X93		6492BR
Secondary .....	37X92		6491BR
<b>521613X71A; 521613X89A; 521613X89B; 521613X189A</b>			
Drive .....	37X97		6432BR
Primary .....	37X93		6492BR
Secondary .....	37X92		6491BR
<b>2550092A</b>			
Deck .....	37X12		6449BR
Drive .....	37X65		6453BR
<b>3371206; 3391107</b>			
Motion Drive .....	37X65		6453BR
<b>3394308</b>			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X62		6400BR
<b>3395606</b>			
Motion Drive .....	37X61		6452BR
<b>3396201</b>			
Deck .....	37X70		6603BR
Drive .....	37X61		6452BR
<b>MUSTANG</b>			
<b>245; 248; 248E</b>			
Eng. To Trans. ....		2310	6831
<b>NATIONAL MOWER</b>			
<b>68" Triplex</b>			
Eng.; W/7.5 H.P. Eng. ....			6844
Eng.; W/8 H.P. Eng. ....	A338		AX38
High Speed Wing Mower; W/7.5 H.P. Eng. ....			6838
Eng. ....	A36		6831
J.S.; W/7.5 H.P. Eng. ....	A29		6831
J.S.; W/8 H.P. Eng. ....	D335		6969
Main Drive; W/7.5 H.P. Eng. ....	B66		6969
Main Drive; W/8 H.P. Eng. ....	A339		6844
Rear Mower; W/7.5 H.P. Eng. ....			6843
Rear Mower; W/8 H.P. Eng. ....	E310		6837
Wing Mower; W/7.5 H.P. Eng. ....	A35		6838
Wing Mower; W/8 H.P. Eng. ....	E373B		
<b>70" Hydro Triplex</b>			
Front Mower; W/16 H.P. Eng. ....			BX58
P.T.O.; W/16 H.P. Eng. ....			6840
<b>84" Triplex</b>			
Eng.; W/10, 12 H.P. Eng. ....	AA805		6847
Eng.; W/16 H.P. Eng. ....			6850
High Speed Drive; W/10, 12 H.P. Eng. ....	AA806		6842
Main Drive; W/10, 12 H.P. Eng. ....			6988
Main Drive; W/16 H.P. Eng. ....	B83		6986
Rear Mower; W/10, 12 H.P. Eng. ....	E346B		6950
Rear Mower; W/16 H.P. Eng. ....			6950
Transport Pump; W/16 H.P. Eng. ....			6844
Wing Mower; W/10, 12 H.P. Eng. ....	E346A		6945
Wing Mower; W/16 H.P. Eng. ....			6946
<b>NEW HOLLAND</b>			
<b>EGT80; EGT100</b>			
Belt; W/44" Belt O.C. ....	120174		6844
<b>EGT120</b>			
Belt; W/34" Belt O.C. ....	120454		6734
<b>EGT150</b>			
Belt; W/40" Belt O.C. ....	120453		3V400

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NEW HOLLAND - Continued</b>			
<b>MC22</b>			
Fan .....	SBA080109049	7300	
<b>MC28</b>			
Fan .....	86517953		AX34
<b>MC35</b>			
Fan .....	86517954		AX36
<b>S12; S14</b>			
Belt; W/35" Belt O.C. ....	174718		6835
<b>NEW IDEA</b>			
<b>EGT20</b>			
Drive .....	120454		6734
<b>EGT80; EGT100</b>			
Drive .....	120174		6844
<b>EGT150; EGT200</b>			
Drive .....	120453		3V400
<b>EGTR36</b>			
Drive .....	121279		6834
<b>NOMA</b>			
<b>12-40 (A4012-020); 16-40 (A4016-000)</b>			
Blade .....	48044		6454BR
<b>822-254</b>			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	57214		6775BR
<b>850-4847</b>			
Blade .....			6975
Trans. ....	54758		6551BR
<b>2235-000; 2235-001</b>			
Blade; W/24" Blade .....	20368	2290	
<b>2236-0000</b>			
Blade; W/24" Blade .....	20368	2290	
Drive; W/24" Blade .....	23164		6825
<b>2650-000; 2650-0200; 2650-0300; 2650-0400</b>			
Blade; W/26" Blade .....	55442		6858
Trans.; W/26" Blade .....	55450		6842
<b>2650-0700</b>			
Blade; W/26" Blade .....	300749		6847
Trans.; W/26" Blade .....	300575		6836
<b>2650-0800</b>			
Deck .....	300749		6847
<b>2650-1100; 2650-1101</b>			
Blade; W/26" Blade .....	300749		6847
Trans.; W/26" Blade .....	300575		6836
<b>3010-00; 3010-810</b>			
Deck; W/36" Deck; W/39" Blade .....	305698		6873
<b>3108-0100; 3181-000; 3181-0100; 3181-0200; 3181-0300</b>			
Trans.; W/42" Blade .....			6888
<b>3181-0400</b>			
Trans.; W/42" Blade .....	52842		6896
<b>3182-0100</b>			
Trans.; W/42" Blade .....			6888
<b>3184-0000</b>			
Blade; W/42" Blade .....			6971
Trans.; W/42" Blade .....			6856
<b>3188-0100; 3188-0300; 3188-0600</b>			
Blade; W/42" Blade .....	49878		6467BR
Trans.; W/42" Blade .....	39454		6463BR
<b>3188-0800</b>			
Blade; W/42" Blade .....			6971
Trans.; W/42" Blade .....	39454		6463BR
<b>3188-1400</b>			
Blade .....			6971



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>3188-1500</b>			
Blade .....			6971
Trans. .... 50737			6884
<b>3188-1600</b>			
Blade; W/36" Blade .....			6971
Drive; W/30" Belt O.C.; W/36" Blade .....	53499		6830
Drive; W/69" Belt O.C.; W/36" Blade .....			6869
<b>3188-1700</b>			
Blade; W/36" Blade .....	49878		6467BR
Drive; W/36" Blade .....	53499		6830
<b>3188-1800</b>			
Blade .....			6971
Trans. .... 50737			6884
<b>3188-2000</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	54758		6551BR
<b>3188-5000; 3188-5001</b>			
Blade; W/36" Blade .....	49878		6467BR
Fan; W/36" Blade .....	53443		6734
J.S.; W/36" Blade .....	53162		6850
<b>3189-0000; 3189-0200</b>			
Blade; W/32" Blade .....			6971
Trans.; W/32" Blade .....			6856
<b>3189-0300; 3189-0400; 3189-0500; 3189-0600</b>		2630	
Blade; W/32" Blade .....	45186		6856
Trans.; W/32" Blade .....			
<b>3189-0700; 3189-0701</b>			
Blade; W/32" Blade .....			6971
Trans.; W/32" Blade .....			6856
<b>3189-0900</b>		2630	
Blade; W/32" Blade .....	45186		6856
Trans.; W/32" Blade .....			
<b>3208-0000; 3208-0100; 3208-0200; 3208-0300; 3208-0600; 3208-0800; 3210-0000; 3210-0001</b>		2630	
Blade; W/32" Blade .....	45186		6551BR
Trans.; W/32" Blade .....	54758		
<b>3210-5000; 3210-5100</b>			
Blade; W/26" Blade .....	53833		6881
Trans.; W/26" Blade .....	55450		6842
<b>3210-5200; 3210-5300; 3210-5400; 3210-5500; 3210-5600</b>			
Blade; W/26" Blade .....	48044		6454BR
Trans.; W/26" Blade .....	303241		6890
<b>3280-0000</b>			
Blade; W/26" Blade .....	53833		6881
Trans.; W/26" Blade .....	55450		6842
<b>3280-020</b>			
Blade; W/26" Blade .....	300747		6869
Trans.; W/26" Blade .....	300575		6836
<b>3280-0100; 3280-0200; 3280-0300; 3280-0400; 3280-0500; 3280-0600; 3280-0601</b>			
Blade; W/26" Blade .....	53833		6881
Trans.; W/26" Blade .....	55450		6842
<b>3280-0700; 3280-0800; 3280-0900</b>			
Blade; W/26" Blade .....	300747		6869
Trans.; W/26" Blade .....	300575		6836
<b>3280-1200</b>			
Blade; W/26" Blade .....	300747		6869
Deck .....	300747		6869
Trans.; W/26" Blade .....	300575		6836
<b>3280-1300; 3280-1400; 3280-1700; 3280-1800</b>			
Blade; W/26" Blade .....	300747		6869
Trans.; W/26" Blade .....	300575		6836
<b>3294-0000; 3294-0100</b>			
Blade; W/26" Blade .....	47611		6463BR
Trans.; W/26" Blade .....	51855		6841

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>3362-05</b>			
Blade; W/36" Blade .....	305698		6873
Trans.; W/36" Blade .....	300575		6836
<b>3402-05; 3402-015</b>			
Blade; W/40" Blade .....	48044		6454BR
Trans.; W/40" Blade .....	303241		6890
<b>3506-0600</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....			6856
<b>3560-0470; 3560-2600</b>			
Deck .....	300680		6408BR
Drive .....	57214		6775BR
<b>3560-8400</b>			
Deck .....	48044		6454BR
Drive .....	54758		6551BR
<b>3576-0900</b>			
Trans.; W/42" Blade .....	39454		6463BR
<b>3595-1000</b>			
Blade; W/32" Blade .....	47611		6463BR
Trans.; W/32" Blade .....	55450		6842
<b>3601-0000; 3601-0100; 3601-0101</b>			
Blade; W/36" Blade .....	305698		6873
Trans.; W/36" Blade .....	300575		6836
<b>3610-0000; 3610-0100; 3610-0101; 3610-0200; 3610-0300; 3610-0400; 3610-0500; 3610-0600</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	54758		6551BR
<b>3610-0700; 3610-0800; 3610-0900; 3610-1100; 3610-1300</b>			
Blade; W/36" Blade .....			6975
Trans.; W/36" Blade .....	54758		6551BR
<b>3611-4300; 3611-5300; 3612-2500</b>			
Deck .....	58170		6675BR
<b>3612-3400</b>			
Deck .....	300680		6408BR
Drive .....	57214		6775BR
<b>3812-060</b>			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
<b>3912-2600; 3912-2602; 3912-2603; 3912-2604; 3912-3400; 3912-4100; 3918-0100</b>			
Deck .....	300680		6408BR
Drive .....	57214		6775BR
<b>4015-0300</b>			
Deck .....	48044		6454BR
<b>4516-000</b>			
Blade; W/40 1/2" Belt O.C. ....	300142		6741
Blade; W/78" Belt O.C. ....			6978
Trans. ....			6885
<b>4518-0100; 4518-0300; 4518-0400</b>			
Blade; W/40 1/2" Belt O.C. ....	300142		6741
Blade; W/78" Belt O.C. ....			6978
Trans. ....	57556		6889
<b>4518-0500</b>			
Blade; W/40 1/2" Belt O.C. ....	300142		6741
Blade; W/75" Belt O.C. ....			6975
Trans. ....	57556		6889
<b>4518-0600</b>			
Blade; W/40 1/2" Belt O.C. ....	300142		6741
Blade; W/78" Belt O.C. ....			6978
Trans. ....	57556		6889
<b>4518-0800; 4518-0801</b>			
Blade; W/40 1/2" Belt O.C. ....	300142		6741
Blade; W/75" Belt O.C. ....			6975
Trans. ....			6885
<b>4518-0900</b>			
Blade; W/40 1/2" Belt O.C. ....	300142		6741

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>4518-0900 - Continued</b>			
Blade; W/75" Belt O.C. ....			6975
Trans. ....			6888
<b>4518-1100</b>			
Blade; W/40 1/2" Belt O.C. ....	300142		6741
Blade; W/78" Belt O.C. ....			6978
Trans. ....	57556		6889
<b>4518-1200</b>			
Deck; W/18 H.P. Eng.; W/45" Deck .....			6978
Trans.; W/18 H.P. Eng.; W/45" Deck .....			6889
<b>4518-1300</b>			
Deck; W/18 H.P. Eng.; W/45" Deck .....			6978
Trans.; W/18 H.P. Eng.; W/45" Deck .....			6891
<b>4518-2200</b>			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	302719		6891
<b>4518-2400</b>			
Trans. ....			6885
<b>4518-2600</b>			
Blade; W/40 1/2" Belt O.C. ....	300142		6741
Blade; W/75" Belt O.C. ....			6975
Trans. ....	57556		6889
<b>4518-2700</b>			
Trans. ....	57556		6889
<b>4518-6000</b>			
Blade .....			6975
Trans. ....	50737		6884
<b>5137-0000</b>			
Blade; W/24" Blade .....	45187	2440	
Trans.; W/24" Blade .....			6856
<b>5180-0000; 5180-0100; 5180-0400; 5180-0700;</b>			
<b>5181-0000; 5181-0100; 5181-0200; 5181-0300;</b>			
<b>5181-0500; 5181-0600</b>			
Trans. ....			6888
<b>5181-0900; 5181-1100; 5181-1200; 5181-1201</b>			
Trans. ....			6888
<b>5181-1300; 5181-1301</b>			
Trans. ....	52842		6896
<b>5181-1400; 5181-1500</b>			
Trans. ....			6888
<b>5181-1501</b>			
Trans.; W/42" Blade .....			6888
<b>5181-1600</b>			
Trans.; W/42" Blade .....	52842		6896
<b>5182-0000; 5182-0100; 5182-0200; 5182-0300;</b>			
<b>5182-0400; 5182-0500; 5182-0501</b>			
Trans. ....			6888
<b>5182-0600; 5182-0700</b>			
Blade; W/42" Blade .....	45186	2630	
Trans.; W/42" Blade .....			6856
<b>5182-0800</b>			
Trans. ....			6888
<b>5182-0900</b>			
Blade; W/42" Blade .....	45186	2630	
Trans.; W/42" Blade .....			6856
<b>5184-0000; 5184-0100; 5184-0400; 5184-0500;</b>			
<b>5184-0600; 5184-0700; 5184-0701; 5184-0800;</b>			
<b>5184-0900; 5184-1000</b>			
Blade; W/42" Blade .....	49878		6467BR
Trans.; W/42" Blade .....			6856
<b>5184-1200</b>			
Blade; W/42" Blade .....	49878		6467BR
Trans.; W/42" Blade .....			6856

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>5188-0000</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5188-0200</b>			
Trans.; W/42" Blade .....	39454		6463BR
<b>5188-0300; 5188-0600; 5188-0700; 5188-0800;</b>			
<b>5188-0900; 5188-1000</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5188-1100</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	39454		6463BR
<b>5188-1300; 5188-1400; 5188-1500</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5188-1700</b>			
Trans.; W/42" Blade .....	39454		6463BR
<b>5188-2000</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5188-2100</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	39454		6463BR
<b>5188-2200; 5188-2300; 5188-2400</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5188-2500; 5188-2501</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	50737		6884
<b>5188-2600</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	50737		6884
<b>5188-2601; 5188-2700; 5188-2701</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	50737		6884
<b>5188-2900</b>			
Trans.; W/42" Blade .....	50737		6884
<b>5188-3000</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	50737		6884
<b>5188-3001; 5188-3002; 5188-3100; 5188-3101;</b>			
<b>5188-3102; 5188-3103</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	50737		6884
<b>5188-3300</b>			
Trans.; W/42" Blade .....	50737		6884
<b>5188-3400</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/30" Belt O.C.; W/36" Blade .....	50597		6830
Blade .....	49580	2405	
<b>5188-3500</b>			
Blade; W/36" Blade .....			6971
<b>5188-3600; 5188-3700</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	50737		6884
<b>5188-3800</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	50737		6884
<b>5188-3900</b>			
Blade; W/36" Blade .....	49878		6467BR
<b>5188-4000</b>			
Blade; W/36" Blade .....			6971
<b>5188-4200; 5188-4300; 5188-4301</b>			
Blade; W/36" Blade .....	49878		6467BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>5188-4500</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade; W/30" Belt O.C. ....	53499		6830
Trans.; W/36" Blade; W/69" Belt O.C. ....			6869
<b>5188-4600</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade; W/30" Belt O.C. ....	53499		6830
Trans.; W/36" Blade; W/69" Belt O.C. ....			6869
<b>5188-4700; 5188-4900</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	50737		6884
<b>5188-4901</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	53833		6881
<b>5188-4902; 5188-4903</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	50737		6884
<b>5188-5000</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	50737		6884
<b>5188-5100; 5188-5101</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	53499		6830
<b>5188-5200</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade; W/30" Belt O.C. ....	53499		6830
Trans.; W/36" Blade; W/69" Belt O.C. ....			6869
<b>5188-5300</b>			
Trans.; W/42" Blade; W/30" Belt O.C. ....	53499		6830
Trans.; W/42" Blade; W/69" Belt O.C. ....			6869
<b>5188-5600</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	50737		6884
<b>5188-5700</b>			
Trans.; W/42" Blade; W/30" Belt O.C. ....	53499		6830
Trans.; W/42" Blade; W/69" Belt O.C. ....			6869
<b>5188-5900</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	50737		6884
<b>5188-6000</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	54758		6551BR
<b>5188-6100</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	54758		6551BR
<b>5188-6200</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	54758		6551BR
<b>5188-6300</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	54758		6551BR
<b>5188-6400; 5188-6401</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	54758		6551BR
<b>5188-6500</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	54758		6551BR
<b>5188-6600; 5188-6601</b>			
Trans.; W/36" Blade .....			6871
<b>5188-6700</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	50737		6884
<b>5188-6800</b>			
Trans.; W/36" Blade .....			6871
<b>5188-6801</b>			
Blade; W/36" Blade .....	49878		6467BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>5188-6801 - Continued</b>			
Trans.; W/36" Blade .....	54758		6551BR
<b>5188-6900</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	54830		6871
<b>5188-7500; 5188-7501; 5188-7600</b>			
Blade; W/36" Blade .....	49878		6467BR
<b>5188-8000</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	54758		6551BR
<b>5188-8100</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	54758		6551BR
<b>5188-8200</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	54758		6551BR
<b>5188-8300</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	54758		6551BR
<b>5188-8400</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	54830		6871
<b>5188-9000</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	49580	2405	
<b>5188-9100; 5188-9101</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....			6869
<b>5188-9200; 5188-9300</b>			
Blade; W/36" Blade .....	49878		6467BR
Trans.; W/36" Blade .....	50737		6884
<b>5218-4100; 5218-4200; 5218-4300; 5218-4400; 5218-4500; 5218-4600; 5218-4700; 5218-4800; 5218-4900</b>			
Blade; W/36" Blade .....	46466		6983
Drive; W/36" Blade .....	39454		6463BR
<b>5236-0; 5236-0000; 5236-0100; 5236-0200; 5236-0400; 5236-3200</b>			
Blade; W/32" Blade .....	20368	2290	
<b>5238-0000; 5238-0200; 5238-3000; 5238-3200; 5238-4000</b>			
Blade; W/32" Blade .....	20368	2290	
Drive; W/32" Blade .....	23164		6825
<b>5239-0000; 5239-4000; 5239-4200; 5240-0000; 5240-0200; 5240-3000</b>			
Drive; W/32" Blade .....	20368	2290	
<b>5244-3000; 5244-3200; 5244-3400</b>			
Blade; W/24" Blade .....	20368	2290	
Drive; W/24" Blade .....	23164		6825
<b>5246-0000; 5246-0100; 5246-3000; 5246-3100; 5246-3200; 5246-3400</b>			
Drive; W/30" Blade .....	26659	3720	
<b>5252-0000</b>			
Blade; W/30" Blade .....	47611		6463BR
Drive; W/30" Blade .....			6841
<b>5254-0000; 5254-3100; 5255-0000; 5255-4200; 5258-0000; 5258-4200; 5258-4400</b>			
Blade; W/24", 26" Blade .....	29798		6827
<b>5260-0000</b>			
Deck; W/24" Blade .....	29798		6827
<b>5261-0000</b>			
Blade; W/24", 26" Blade .....	29798		6827
<b>5267-0910</b>			
Blade; W/26" Blade .....	45187	2440	
Trans.; W/26" Blade .....			6856

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>5267-1400</b>			
Blade; W/32" Blade .....	45186	2630	
Trans.; W/32" Blade .....			6856
<b>5267-1500</b>			
Blade; W/26" Blade .....	45187	2440	
Trans.; W/26" Blade .....			6856
<b>5267-1900</b>			
Blade; W/32" Blade .....	47390		6871
Trans.; W/32" Blade .....			6856
<b>5267-2000; 5267-2100</b>			
Blade; W/32" Blade .....	45186	2630	
Trans.; W/32" Blade .....			6856
<b>5267-9000</b>			
Blade; W/26" Blade .....	45187	2440	
Trans.; W/26" Blade .....			6856
<b>5268-0000</b>			
Blade; W/32" Blade .....			6863
Trans.; W/32" Blade .....			6856
<b>5268-0100</b>			
Blade; W/26" Blade .....	44039		6844
Trans.; W/26" Blade .....			6856
<b>5268-0200; 5268-0400</b>			
Blade; W/32" Blade .....			6863
Trans.; W/32" Blade .....			6856
<b>5268-0500</b>			
Blade; W/26" Blade .....	45187	2440	
Trans.; W/26" Blade .....			6856
<b>5268-0600; 5268-0700; 5268-0800; 5268-0900;</b>			
<b>5268-1100; 5268-1200</b>			
Blade; W/26" Blade .....	45186	2630	
Trans.; W/26" Blade .....			6856
<b>5270-0200; 5270-3300; 5270-3500; 5270-3800</b>			
Blade; W/24" Blade .....	31053		6827
Drive; W/24" Blade .....	30997		6847
<b>5271-0000; 5271-0100; 5271-0200; 5271-0300;</b>			
<b>5271-3300; 5271-3500; 5271-3900; 5271-4100;</b>			
<b>5271-4200; 5271-4300</b>			
Blade; W/26" Blade .....	31053		6827
Drive; W/26" Blade .....	30998		6842
<b>5271-4600; 5271-4700; 5271-4800; 5271-4900;</b>			
<b>5274-0000; 5274-0100; 5275-000</b>			
Blade; W/26" Blade .....	31053		6827
Drive; W/26" Blade .....	30998		6842
<b>5276-0000; 5276-040</b>			
Blade; W/26" Blade .....	41505		6835
Drive; W/26" Blade .....	30998		6842
<b>5276-0100</b>			
Blade; W/36" Blade .....	45187	2440	
Trans.; W/36" Blade .....			6856
<b>5276-0200; 5276-0300</b>			
Blade; W/26" Blade .....	41505		6835
Blade; W/36" Blade .....	45187	2440	
Drive; W/26" Blade .....	30998		6842
Trans.; W/36" Blade .....			6856
<b>5276-0400</b>			
Blade; W/36" Blade .....	45187	2440	
Trans.; W/36" Blade .....			6856
<b>5276-0500; 5276-0600; 5276-0800</b>			
Blade; W/26" Blade .....	41505		6835
Blade; W/36" Blade .....	45187	2440	
Drive; W/26" Blade .....	30998		6842
Trans.; W/36" Blade .....			6856
<b>5276-0900</b>			
Blade; W/36" Blade .....	45187	2440	
Trans.; W/36" Blade .....			6856
<b>5276-1000</b>			
Blade; W/32" Blade .....	47390		6871

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>5276-1000 - Continued</b>			
Trans.; W/32" Blade .....			6856
<b>5277-0000; 5277-0100; 5277-0200</b>			
Blade; W/26" Blade .....	41505		6835
Drive; W/26" Blade .....	30998		6842
<b>5278-0100</b>			
Blade; W/26" Blade .....	31053		6827
Drive; W/26" Blade .....	30998		6842
<b>5281-0000; 5281-0100; 5281-0200</b>			
Blade; W/36" Blade .....	39456	3690	
Drive; W/36" Blade .....	39455		6863
<b>5281-0300</b>			
Blade; W/36" Blade .....	42111		6630BR
Drive; W/36" Blade .....	39455		6863
<b>5281-1000</b>			
Blade; W/36" Blade .....	39456	3690	
Drive; W/36" Blade .....	39455		6863
<b>5282-0000; 5282-0100; 5282-0200; 5282-0300</b>			
Blade; W/36" Blade .....	39456	3690	
Drive; W/36" Blade .....	39454		6463BR
<b>5282-0400; 5282-0500; 5282-0600; 5282-0700</b>			
Blade; W/36" Blade .....	42111		6630BR
Drive; W/36" Blade .....	39454		6463BR
<b>5282-0800; 5282-0900</b>			
Blade; W/36" Blade .....			6971
Drive; W/36" Blade .....	39454		6463BR
<b>5282-1000; 5282-1100</b>			
Blade; W/36" Blade .....	39456	3690	
Drive; W/36" Blade .....	39454		6463BR
<b>5282-1200</b>			
Blade; W/36" Blade .....	42111		6630BR
Drive; W/36" Blade .....	39454		6463BR
<b>5282-1201</b>			
Blade; W/36" Blade .....	39456	3690	
Drive; W/36" Blade .....	39454		6463BR
<b>5282-1400</b>			
Blade; W/36" Blade .....	42111		6630BR
Drive; W/36" Blade .....	39454		6463BR
<b>5282-1600; 5282-1800</b>			
Blade; W/36" Blade .....			6971
Drive; W/36" Blade .....	39454		6463BR
<b>5282-2000</b>			
Blade; W/36" Blade .....	39456	3690	
Drive; W/36" Blade .....	39454		6463BR
<b>5282-2200; 5282-2300</b>			
Blade; W/36" Blade .....			6971
Drive; W/36" Blade .....	39454		6463BR
<b>5282-2500</b>			
Blade; W/36" Blade .....	48044		6454BR
Drive; W/36" Blade .....	39454		6463BR
<b>5283-0000; 5283-0100; 5283-0200</b>			
Blade; W/36" Blade .....	39456	3690	
Drive; W/36" Blade .....	39455		6863
<b>5283-0300; 5283-0500</b>			
Blade; W/36" Blade .....	42111		6630BR
Drive; W/36" Blade .....	39455		6863
<b>5283-1000</b>			
Blade; W/36" Blade .....	39456	3690	
Drive; W/36" Blade .....	39455		6863
<b>5284-0000; 5284-0100; 5285-0000; 5285-0100;</b>			
<b>5285-0200; 5285-0300</b>			
Blade; W/36" Blade .....	39456	3690	
Drive; W/36" Blade .....	39454		6463BR
<b>5285-0400; 5285-0500; 5285-0600; 5285-0700;</b>			
<b>5285-0800; 5285-0900</b>			
Blade; W/36" Blade .....	42111		6630BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>5285-0400; 5285-0500; 5285-0600; 5285-0700; 5285-0800; 5285-0900 - Continued</b>			
Drive; W/36" Blade .....	39454		6463BR
<b>5285-1000; 5285-1100; 5285-1201; 5285-1300</b>		3690	
Blade; W/36" Blade .....	39456		
Drive; W/36" Blade .....	39454		6463BR
<b>5285-1400</b>			
Blade; W/36" Blade .....	42111		6630BR
Drive; W/36" Blade .....	39454		6463BR
<b>5285-1500; 5285-1600; 5285-1700; 5285-2000; 5285-2200; 5285-2300; 5285-2500; 5285-2600; 5285-2700; 5285-2800</b>			
Blade; W/36" Blade .....			6971
Drive; W/36" Blade .....	39454		6463BR
<b>5285-2900; 5285-3000; 5285-3200; 5285-3300; 5285-3400; 5285-3600; 5285-3900; 5285-4000</b>			
Blade; W/36" Blade .....			6971
Drive; W/36" Blade .....	39454		6463BR
<b>5285-5000</b>			
Blade; W/36" Blade .....	48044		6454BR
Drive; W/36" Blade .....	39454		6463BR
<b>5285-5100</b>			
Blade; W/36" Blade .....			6971
Drive; W/36" Blade .....	39454		6463BR
<b>5285-5200</b>			
Blade; W/36" Blade .....	48044		6454BR
Drive; W/36" Blade .....	39454		6463BR
<b>5285-5300; 5285-5400</b>			
Blade; W/36" Blade .....			6971
Drive; W/36" Blade .....	39454		6463BR
<b>5285-5600; 5285-5800; 5285-5801; 5285-5900; 5285-6000; 5285-6200</b>			
Blade; W/36" Blade .....	48044		6454BR
Drive; W/36" Blade .....	39454		6463BR
<b>5288-0000; 5288-0200; 5288-0300; 5288-0500; 5288-0600</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-0700; 5288-0800; 5288-1000; 5288-1100</b>			
Blade; W/36" Blade .....	46466		6983
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-1200; 5288-1300; 5288-1301; 5288-1400; 5288-1500</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-1600</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-1700; 5288-1800; 5288-1900</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-2000</b>			
Blade; W/36" Blade .....	47390		6871
Trans.; W/36" Blade .....			6856
<b>5288-2100</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-2300; 5288-2301; 5288-2400; 5288-2401; 5288-2402; 5288-2600; 5288-2800; 5288-3000</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-3100</b>			
Blade; W/42" Blade; W/53" Belt O.C. ....			6853
Blade; W/42" Blade; W/98" Belt O.C. ....			6898
Trans.; W/42" Blade .....	39454		6463BR
<b>5288-3300; 5288-3400; 5288-3500; 5288-3600</b>			
Blade; W/36" Blade .....	48044		6454BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>5288-3300; 5288-3400; 5288-3500; 5288-3600 - Continued</b>			
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-3700</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-3800; 5288-4000</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-4100</b>			
Trans.; W/42" Blade .....	29454		6463BR
<b>5288-4200; 5288-4300</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-4400</b>			
Trans.; W/42" Blade .....	29454		6463BR
<b>5288-4500; 5288-4700</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-4800</b>			
Trans.; W/42" Blade .....	29454		6463BR
<b>5288-4900; 5288-5000</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-5100; 5288-5101; 5288-5102</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-5200</b>			
Trans.; W/42" Blade .....	29454		6463BR
<b>5288-5500; 5288-5501</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	52467		6887
<b>5288-5600</b>			
Blade; W/36" Blade .....			6971
Trans.; W/36" Blade .....	52467		6887
<b>5288-5700; 5288-5701; 5288-5800; 5288-5801</b>			
Trans.; W/36" Blade .....	52467		6887
<b>5288-6200; 5288-6201</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-6300</b>			
Trans.; W/42" Blade .....	39454		6463BR
<b>5288-6400</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5288-6500</b>			
Trans.; W/42" Blade .....	29454		6463BR
<b>5288-9100</b>			
Blade; W/36" Blade .....	48044		6454BR
Trans.; W/36" Blade .....	39454		6463BR
<b>5289-0000; 5289-0100</b>			
Blade; W/32" Blade .....			6863
Trans.; W/32" Blade .....			6856
<b>5289-0200</b>			
Blade; W/32" Blade .....	45186		6863
Trans.; W/32" Blade .....			6856
<b>5289-0300</b>			
Blade; W/32" Blade .....			6863
Trans.; W/32" Blade .....			6856
<b>5289-0400; 5289-0500; 5289-0700; 5289-0800; 5289-1200; 5289-1400; 5289-1500</b>			
Blade; W/32" Blade .....	45186	2630	
Trans.; W/32" Blade .....			6856

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
5289-1600; 5289-1700; 5289-1800; 5289-1900; 5289-2000; 5289-2100; 5289-2300; 5289-2500; 5289-2600; 5289-2601			
Blade; W/32" Blade .....	47390		6871
Trans.; W/32" Blade .....			6856
5289-2800; 5289-2900; 5289-3000; 5289-3100; 5289-3200; 5289-3300; 5289-3400; 5289-3401; 5289-3600; 5289-3700			
Blade; W/32" Blade .....	47390		6871
Trans.; W/32" Blade .....			6856
5289-3800; 5289-4000; 5289-4100; 5289-4200; 5289-4201; 5289-4300; 5289-4301; 5289-4500; 5289-4501; 5289-4600			
Blade; W/32" Blade .....	47390		6871
Trans.; W/32" Blade .....			6856
5289-4700; 5289-5100; 5289-5101; 5289-5102			
Blade; W/32" Blade .....	47390		6871
Trans.; W/32" Blade .....			6856
5289-5200			
Blade; W/32" Blade .....	45186	2630	
Trans.; W/32" Blade .....			6856
5289-5400			
Blade; W/32" Blade .....	47390		6871
Trans.; W/32" Blade .....			6856
5289-5500; 5289-5600			
Blade; W/32" Blade .....	45186	2630	
Trans.; W/32" Blade .....			6856
5289-5700; 5289-9100			
Blade; W/32" Blade .....	47390		6871
Trans.; W/32" Blade .....			6856
5290-0000; 5290-1100; 5290-1200; 5290-1300; 5290-2000; 5290-2100			
Blade; W/32" Blade .....	42846		6850
Trans.; W/32" Blade .....	42858	2390	
5293-0000; 5293-2000			
Blade; W/32" Blade .....	42881		6971
Trans.; W/32" Blade .....	42858	2390	
5294-0200; 5294-0300; 5294-0400; 5294-0600			
Blade; W/32" Blade .....	45186	2630	
Trans.; W/32" Blade .....			6841
5294-0900			
Blade; W/32" Blade .....	47611		6463BR
Trans.; W/32" Blade .....			6841
5294-1700; 5294-1800; 5294-2000; 5294-2100; 5294-2200; 5294-2300			
Blade; W/32" Blade .....	47611		6463BR
Trans.; W/32" Blade .....	51855		6841
5296-0000; 5296-0200			
Blade; W/32" Blade .....			6971
Trans.; W/32" Blade .....	39454		6463BR
5296-0300			
Blade; W/32" Blade .....	47611		6463BR
Trans.; W/32" Blade .....			6841
5296-0400			
Blade; W/32" Blade .....			6971
Trans.; W/32" Blade .....	39454		6463BR
5296-0700; 5296-0800			
Blade; W/32" Blade .....	46466		6983
Trans.; W/32" Blade .....	39454		6463BR
5296-0900; 5296-1000; 5296-1200			
Blade; W/32" Blade .....	48044		6454BR
Trans.; W/32" Blade .....	39454		6463BR
5297-0000; 5297-0100; 5297-0200; 5297-0300; 5297-0400; 5297-0500			
Blade; W/42" Blade .....	44313		6852
Trans.; W/88" Belt O.C.; W/42" Blade .....	39454		6463BR
Trans.; W/98" Belt O.C.; W/42" Blade .....			6898

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
5297-0600; 5297-0700; 5297-1000; 5297-1100; 5297-1200; 5297-1300			
Blade; W/53" Belt O.C.; W/42" Blade .....			6853
Blade; W/98" Belt O.C.; W/42" Blade .....			6898
Trans.; W/42" Blade .....	39454		6463BR
5298-5201			
Blade; W/42" Blade .....	47390		6871
Trans.; W/42" Blade .....			6856
5299-0000			
Blade; W/42" Blade .....	47201		6825
P.T.O.; W/42" Blade .....	47200		6829
8897			
Blade .....			6975
Trans. ....	54758		6551BR
50336			
Trans.; W/24" Blade .....	29798		6827
50337-3			
Blade; W/24" Blade .....	30997		6847
Trans.; W/24" Blade .....	31053		6827
50347-1; 50347-3; 50349-4			
Blade; W/24" Blade .....	30998		6842
Trans.; W/24" Blade .....	31053		6827
503371			
Blade; W/24" Blade .....	30997		6847
Trans.; W/24" Blade .....	31053		6827
A2650-010			
Blade; W/26" Blade .....	309715		6844
Trans.; W/26" Blade .....	300575		6836
A3008-000			
Trans.; W/30" Blade .....	54758		6551BR
Trans.; W/8 H.P. Eng.; W/30" Deck .....	54758		6551BR
A3008-020			
Trans.; W/30" Blade .....	54758		6551BR
A3210-000; A3210-001; A3280-000			
Blade; W/32" Blade .....	300747		6869
Trans.; W/32" Blade .....	300575		6836
A3280-020			
Deck .....	300747		6869
A3554-040			
Blade; W/36" Blade .....	302289		6974
Trans.; W/36" Blade .....	54758		6551BR
A3601-000; A3601-040			
Blade; W/36" Blade .....	305698		6873
Trans.; W/36" Blade .....	300575		6836
A3610-000; A3611-000			
Deck .....	58170		6675BR
Trans. ....	54758		6551BR
A3611-000-020			
Blade .....			6975
Trans. ....	54758		6551BR
A3611-020; A3612-000			
Deck .....	58170		6675BR
A3612-000-010			
Blade .....			6975
Trans. ....	54758		6551BR
A3612-010			
Deck .....	58170		6675BR
A3812-000; A3812-001; A3812-010			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
A3812-020			
Deck .....			6978
Trans. ....			6885
A3812-030; A3812-040; A3812-050; A3812-060; A3812-061			
Deck .....	300680		6408BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
A3812-030; A3812-040; A3812-050; A3812-060; A3812-061 - Continued			
Drive .....	54758		6551BR
A3912-000; A3912-011; A3912-020; A3912-021; A3912-030; A3912-031; A3912-060; A3912-080; A3912-090; A3912-110			
Deck .....	300680		6408BR
Drive .....	57214		6775BR
A3912-111; A3914-000; A3916-000			
Deck .....	300680		6408BR
Drive .....	57214		6775BR
A3917-000			
Deck .....			6978
Trans. ....			6885
A4012-000; A4012-030; A4012-100; A4012-110; A4012-140; A4012-150; A4016-020; A4016-030; A4016-040			
Deck .....	48044		6454BR
A4514-000; A4514-010; A4514-020; A4516-020			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	57214		6775BR
A4518-010			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	57556		6889
A4518-030; A4518-031			
Cross Deck .....	300142		6741
Deck .....	58170		6675BR
Trans. ....	57556		6889
A4518-060; A4518-061			
Cross Deck .....	300142		6741
Deck .....	58170		6675BR
Trans. ....			6885
A4518-080; A4518-081			
Cross Deck .....	300142		6741
Deck .....	58170		6675BR
A4618-010			
Trans.; W/18 H.P. Eng.; W/45" Deck .....	57556		6889
B3010-000; B3080-020			
Trans.; W/30" Blade .....	300575		6836
B3201-010; B3201-020; B3201-030; B3210-000; B3211-000			
Blade; W/32" Blade .....	300747		6869
Trans.; W/32" Blade .....	300575		6836
B3583-230			
Cross Deck .....	300142		6741
Deck .....	58170		6675BR
Trans. ....	302719		6891
B3601-000; B3601-040; B3601-060			
Blade; W/36" Blade .....	305698		6873
Trans.; W/36" Blade .....	300575		6836
B3610-120; B3610-130; B3812-000			
Deck .....	58170		6675BR
Trans. ....	54758		6551BR
B3812-010; B3812-020; B3812-040; B3812-050; B3812-060; B3812-080; B3812-090; B3812-100; B3812-120; B3812-130			
Deck .....	300680		6408BR
Drive .....	54758		6551BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
B3812-140; B3812-150; B3812-160; B3812-170; B3812-180; B3812-190; B3812-200; B3812-210; B3812-220; B3812-230			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
B3912-000; B3912-010; B3912-020; B3912-120			
Deck .....	300680		6408BR
Drive .....	57214		6775BR
B3912-140			
Deck .....	300680		6408BR
Drive .....	314120		6887
B3912-160; B3912-210			
Deck .....	300680		6408BR
Drive .....	57214		6775BR
B3912-230			
Deck .....	300680		6408BR
Drive .....	54758		6882
B3916-000			
Blade .....	305667		6976
Trans. ....	302719		6891
B3918-010			
Deck .....	300680		6408BR
Drive .....	57214		6775BR
B4012-000; B4012-140; B4012-170; B4012-180; B4012-190; B4013-020; B4013-030; B4014-130; B4016-020			
Deck .....	48044		6454BR
B4212-000; B4212-010; B4314-010; B4314-040			
Trans.; W/43" Blade .....			6885
B4514-010			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	57214		6775BR
B4516-000			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	302719		6891
B4518-010			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	57556		6889
B4518-030			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	314120		6887
B4518-040			
Cross Deck .....	300142		6741
Deck .....	58170		6675BR
B4518-050			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	57556		6889
B4518-060			
Cross Deck .....	300142		6741
Deck .....	58170		6675BR
Trans. ....			6885
B4518-070; B4518-071			
Cross Deck .....	300142		6741
Deck .....	58170		6675BR
Trans. ....			6975
B4518-080			
Deck .....	58170		6675BR
Trans. ....	302719		6891

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>B4518-100; B4518-130</b>			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	302719		6891
<b>B4614-000; B4616-030; B4616-070;</b>			
<b>B4618-021</b>			
Blade; W/43" Blade .....	302291		6964
Trans.; W/43" Blade .....	303241		6890
<b>C3011-020; C3012-000; C3012-020</b>			
Blade; W/30" Blade .....			6854
Trans.; W/30" Blade .....	54758		6551BR
<b>C3601-000; C3601-020</b>			
Blade; W/36" Blade .....	320534		6874
<b>C3612-010</b>			
Deck .....	58170		6675BR
Trans. ....	54758		6551BR
<b>C3812-00T; C3812-010; C3812-050;</b>			
<b>C3812-060; C3912-000; C3912-010;</b>			
<b>C3912-060; C3912-090; C3912-110;</b>			
<b>C3912-120</b>			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
<b>C3912-130; C3912-150</b>			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
<b>C3912-200; C3912-400; C3913-000</b>			
Deck .....	300680		6408BR
Drive .....	314120		6887
<b>C4012-010</b>			
Blade; W/40" Blade .....	319005		6981
Trans.; W/40" Blade .....			6887
<b>C4012-020; C4012-050; C4013-000;</b>			
<b>C4013-010; C4013-020; C4013-050</b>			
Deck .....	48044		6454BR
<b>C4136-020; C4136-040; C4212-000;</b>			
<b>C4213-000; C4213-01T</b>			
Blade; W/38" Blade .....	318372		6702BR
Trans.; W/38" Blade .....			6887
<b>C4214-00T</b>			
Blade; W/42", 43" Blade .....	318372		6702BR
Trans.; W/42", 43" Blade .....	314572		6880
<b>C4312-000; C4312-040</b>			
Blade; W/38" Blade .....	318372		6702BR
Trans.; W/38" Blade .....			6887
<b>C4313-000; C4313-030; C4313-051</b>			
Blade; W/42", 43" Blade .....	318372		6702BR
Trans.; W/42", 43" Blade .....	314572		6880
<b>C4314-051; C4318-000; C4318-020</b>			
Blade; W/38" Blade .....	318372		6702BR
Trans.; W/38" Blade .....			6887
<b>C4318-030; C4318-040</b>			
Blade; W/42", 43" Blade .....	318372		6702BR
Trans.; W/42", 43" Blade .....	314572		6880
<b>C4614-030; C4614-030X; C4614-031;</b>			
<b>C4616-03T</b>			
Blade; W/46" Blade .....	321206		6845
Trans.; W/46" Blade .....			6887
<b>C4618-02T</b>			
Blade; W/46" Blade .....	321206		6845
Trans.; W/46" Blade .....	314572		6880
<b>C4618-040; C4618-050</b>			
Blade; W/46" Blade .....	321206		6845
Trans.; W/46" Blade .....	302719		6891
<b>D3011-050</b>			
Trans.; W/30" Blade .....	300575		6836

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>D3554-021</b>			
Blade; W/38", 39" Blade .....			6978
Trans.; W/38", 39" Blade .....	54758		6551BR
<b>D3554-031; D3554-032</b>			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
<b>D3601-000; D3601-020</b>			
Blade; W/36" Blade .....	320534		6874
Trans.; W/36" Blade .....	300575		6836
<b>D3812-000; D3812-030; D3812-040;</b>			
<b>D3813-000</b>			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
<b>D3912-000</b>			
Deck .....	300680		6408BR
Drive .....	314120		6887
<b>D3912-010; D3912-040; D3912-060;</b>			
<b>D3912-070; D3912-071</b>			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
<b>D3912-110</b>			
Deck .....	300680		6408BR
Drive .....	326932		6876
<b>D3912-150</b>			
Deck .....	300680		6408BR
Drive .....	314572		6880
<b>D3912-160; D3912-170</b>			
Deck .....	300680		6408BR
Drive .....	314120		6887
<b>D3912-171</b>			
Blade; W/38", 39" Blade .....			6978
Trans.; W/38", 39" Blade .....	54758		6551BR
<b>D3912-190</b>			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
<b>D3912-210</b>			
Deck .....	300680		6408BR
<b>D3913-000</b>			
Deck .....	300680		6408BR
Drive .....	314120		6887
<b>D4013-020</b>			
Deck .....	48044		6454BR
<b>D4013-060</b>			
Blade; W/40" Blade .....	319005		6981
Trans.; W/40" Blade .....	314572		6880
<b>D4213-000</b>			
Blade; W/42", 43" Blade .....	305148		6983
<b>D4213-020</b>			
Blade; W/42", 43" Blade .....	305148		6983
Trans.; W/42", 43" Blade .....	54758		6551BR
<b>D4214-000</b>			
Blade; W/42", 43" Blade .....	318372		6702BR
Trans.; W/42", 43" Blade .....	314572		6880
<b>D4214-060</b>			
Blade; W/43" Blade .....	318372		6702BR
Trans.; W/43" Blade .....			6887
<b>D4313-020</b>			
Blade; W/42", 43" Blade .....	305148		6983
Trans.; W/42", 43" Blade .....	54758		6551BR
<b>D4313-030; D4313-040</b>			
Blade; W/42", 43" Blade .....	305148		6983
<b>D4313-050</b>			
Blade; W/42", 43" Blade .....	305148		6983
Trans.; W/42", 43" Blade .....	54758		6551BR
<b>D4313-070; D4313-080</b>			
Blade; W/42", 43" Blade .....	318372		6702BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>D4313-070; D4313-080 - Continued</b>			
Trans.; W/42", 43" Blade .....	314572		6880
<b>D4313-090</b>			
Blade; W/42", 43" Blade .....	305148		6983
Trans.; W/42", 43" Blade .....	54758		6551BR
<b>D4314-060</b>			
Blade; W/43" Blade .....	314108		6537BR
Trans.; W/43" Blade .....	314572		6880
<b>D4314-090</b>			
Blade; W/42", 43" Blade .....	318372		6702BR
Trans.; W/42", 43" Blade .....	314572		6880
<b>D4315-000</b>			
Blade; W/43" Blade .....	314108		6537BR
Trans.; W/43" Blade .....			6887
<b>D4316-000</b>			
Blade; W/42", 43" Blade .....	318372		6702BR
Trans.; W/42", 43" Blade .....	314572		6880
<b>D4318-000; D4318-030; D4318-040;</b>			
<b>D4318-050</b>			
Blade; W/43" Blade .....	318372		6702BR
Trans.; W/43" Blade .....			6887
<b>D4318-060</b>			
Blade; W/43" Blade .....	314108		6537BR
Trans.; W/43" Blade .....			6887
<b>D4618-000; D4618-020</b>			
Blade; W/46" Blade .....	321206		6845
Trans.; W/46" Blade .....	302719		6891
<b>DYK117B88</b>			
Blade; W/39" Blade .....			6978
Trans.; W/39" Blade .....			6885
<b>DYK700FA98</b>			
Blade; W/26", 32" Blade .....	300747		6869
Trans.; W/26", 32" Blade .....	300575		6836
<b>DYK7003A98</b>			
Blade; W/26", 32" Blade .....	300749		6847
Trans.; W/26", 32" Blade .....	300575		6836
<b>DYK7007B88</b>			
Deck .....	300680		6408BR
Drive .....	57214		6775BR
<b>DYK7021A98</b>			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	57556		6899
<b>DYK7117A88; DYK7117A98; DYK7117B88</b>			
Deck .....	300680		6408BR
Drive .....	57214		6775BR
<b>DYK7121A98</b>			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	57556		6889
<b>E3812-100; E3912-000; E3912-020;</b>			
<b>E3912-030; E3912-060</b>			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
<b>E3912-400</b>			
Deck .....	300680		6408BR
Drive .....	314572		6880
<b>E3913-030</b>			
Deck .....	300680		6408BR
Drive .....	326932		6876
<b>F3912-000; F3912-020; F3912-030;</b>			
<b>F3912-040; F3912-050</b>			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
<b>F3912-090</b>			
Deck .....	300680		6408BR
Drive .....	338017		6885

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>F3912-100</b>			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
<b>G3912-000; G3912-010; G3912-030;</b>			
<b>G3912-040</b>			
Deck .....	300680		6408BR
Drive .....	338017		6885
<b>LT-1239 (A3912-000)</b>			
Belt; W/39" Deck; W/12 H.P. Eng. ....			6978
Trans.; W/12 H.P. Eng. ....			6884
<b>LT1443</b>			
Blade; W/14 H.P. Eng. ....	48044		6454BR
Trans.; W/14 H.P. Eng. ....	50737		6884
<b>LTI-1646 (A4616-00)</b>			
Blade; W/16 H.P. Eng. ....	48044		6454BR
Trans.; W/16 H.P. Eng. ....	50737		6884
<b>LX-1240 (A4012-020)</b>			
Blade; W/12 H.P. Eng. ....	48044		6454BR
<b>LX-1340 (A4012-010)</b>			
Blade; W/12.5 H.P. Eng. ....	48044		6454BR
Trans.; W/12.5 H.P. Eng. ....	50737		6884
<b>LXI-1440 (A4014-000)</b>			
Blade; W/14 H.P. Eng. ....	48044		6454BR
Trans.; W/14 H.P. Eng. ....	50737		6884
<b>MOM6052A09</b>			
Deck .....	37X12		6449BR
Motion Drive .....	37X65		6453BR
<b>MOM6084A09; MOM6107A49; MOM6115A59;</b>			
<b>MOM6115A89</b>			
Motion Drive .....	37X65		6453BR
<b>NOP711A09</b>			
Blade; W/39" Blade .....			6978
Trans.; W/39" Blade .....			6885
<b>NOP1720A19</b>			
Blade; W/36" Blade .....			6975
Trans.; W/36" Blade .....	54758		6551BR
<b>NOP7117A09; NOP7117A19</b>			
Deck .....	300680		6408BR
Drive .....	57214		6775BR
<b>NOP7120A19</b>			
Deck .....	58170		6675BR
<b>NOP7122A19</b>			
Deck .....	300680		6408BR
Drive .....	54758		6551BR
<b>NOP8184A09; NOP8184A19</b>			
Cross Deck .....	300142		6741
Deck .....	300680		6408BR
Drive .....	57556		6889
<b>NOP9122A19</b>			
Deck .....	300680		6408BR
Drive .....	314120		6887
<b>NOP9128A19</b>			
Blade; W/42" Blade .....	314108		6537BR
Trans.; W/42" Blade .....	314572		6880
<b>NOP9145A09</b>			
Deck .....	48044		6454BR
Drive .....	303241		6890
<b>XL830</b>			
Deck; W/39" Blade .....	L450		6850
<b>OKLAHOMA TIRE &amp; SUPPLY</b>			
<b>3-3033X6; 3-3043X6</b>			
Blade .....	20555		6841
Deck .....			6848
Trans. ....	20716		6837

Lawn & Garden Equipment

RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>OKLAHOMA TIRE &amp; SUPPLY - Continued</b>			
<b>3-3233X6; 4-3233X6</b>			
Blade .....	21059		6844
Deck .....	21058		6863
Trans. ....	20716		6837
<b>5-2513; 5-2513X6</b>			
Blade .....	20717		6856
Trans. ....	20716		6837
<b>5-3033X6</b>			
Blade .....	20555		6841
Deck .....			6848
Trans. ....	20716		6837
<b>6-2513; 6-2513X6</b>			
Blade .....	20717		6856
Trans. ....	20716		6837
<b>6-3033X6</b>			
Blade .....	20555		6841
Deck .....			6848
Trans. ....	20716		6837
<b>6-3666; 6-3667; 7-3666; 7-3667</b>			
Blade .....			6846
Deck .....	21649		6449BR
Trans. ....	21615		6895
<b>45-340-1</b>			
Gen. ....	7540134	7330	
<b>45-345-9</b>			
P.T.O. ....	7540165		6834
<b>47-200</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>47-201</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>47-202</b>			
Blade .....	7540151		6967
Trans. ....	7540136		6931
Variable Speed .....	7540138	3500	6950
<b>47-206</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>47-215; 47-215-1</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>47-244-0</b>			
J.S. ....	7540245		6859
Trans. ....	7540244		6840
<b>130-350</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>130-360</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>130-380</b>			
Blade .....	7540145		6488BR
Drive .....	7540147	3520	6952
Trans. ....	7540136		6931
<b>130-410</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>130-415</b>			
Blade .....	7540147	3520	6952
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>130-420; 130-430</b>			
Blade .....	7540127		6966
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>OKLAHOMA TIRE &amp; SUPPLY - Continued</b>			
<b>130-460; 130-470</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>130-490</b>			
Blade .....	7540145		6488BR
Drive .....	7540147	3520	6952
Trans. ....	7540136		6931
<b>131-340</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>131-360; 131-412</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>131-418</b>			
Blade .....	7540147	3520	6952
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>131-425; 131-435</b>			
Blade .....	7540127		6966
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>131-480; 131-485; 131-490; 131-495</b>			
Blade .....	7540145		6488BR
Drive .....	7540147	3520	6952
Trans. ....	7540136		6931
<b>132-360</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>132-410</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>132-418</b>			
Blade .....	7540147	3520	6952
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>132-425</b>			
Blade .....	7540127		6966
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>132-495</b>			
Blade .....	7540145		6488BR
Trans. ....	7540136	3500	6931
Variable Speed .....	7540138		6950
<b>133-360</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>133-380; 133-390</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>133-404; 133-410</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>133-420</b>			
Blade .....	7540147	3520	6952
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>133-485</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>134-380</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>134-410</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>134-420</b>			
Blade .....	7540147	3520	6952
Trans. ....	7540136		6931



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>OKLAHOMA TIRE &amp; SUPPLY - Continued</b>			
<b>134-420 - Continued</b>			
Variable Speed .....	7540135		6925
<b>134-460; 134-465</b>			
Blade .....	7540151		6967
Trans. ....	7540136		6931
Variable Speed .....	7540138	3500	6950
<b>135-380A; 135-385A</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>135-390A; 135-395A</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>135-410</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>135-465A</b>			
Blade .....	7540151		6967
Trans. ....	7540136		6931
Variable Speed .....	7540138	3500	6950
<b>136-380A; 136-385A</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>136-390A; 136-395A</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>136-400A</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>136-460A; 136-465A</b>			
Blade .....	7540151		6967
Trans. ....	7540136		6931
Variable Speed .....	7540138	3500	6950
<b>136-504</b>			
Variator .....	7540240		6511BR
<b>137-380A; 137-385; 137-385A</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>137-390; 137-390A; 137-395; 137-395A</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>137-400; 137-400A</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>137-404</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>137-460; 137-460A; 137-465; 137-465A</b>			
Blade .....	7540151		6967
Trans. ....	7540136		6931
Variable Speed .....	7540138	3500	6950
<b>140-659</b>			
Deck .....	7540113	3480	6948
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>140-660</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>140-669</b>			
Deck .....	7540113	3480	6948
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>140-760</b>			
Blade .....	7540125		6428BR
P.T.O. ....	7540123		3V335
<b>140-960</b>			
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>OKLAHOMA TIRE &amp; SUPPLY - Continued</b>			
<b>141-669</b>			
Deck .....	7540113	3480	6948
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>141-760; 141-960</b>			
Blade .....	7540125		6428BR
P.T.O. ....	7540123		3V335
<b>142-960; 143-960</b>			
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>144-672</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Trans. ....	7540182	3810	6981
<b>144-990</b>			
Gen. ....	7540131		6671BR
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>145-660A; 145-672A; 145-760A</b>			
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>145-990A</b>			
Gen. ....	7540131		6671BR
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>147-650; 147-660; 148-650; 148-659; 148-660;</b> <b>148-669; 149-659; 149-669</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>OUR OWN HARDWARE</b>			
<b>130-400</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>130-410</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>130-420; 130-430</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>130-460</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>130-466</b>			
Blade .....	7540151		6957
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>130-470</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>130-480</b>			
Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
<b>130-498</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>130-780</b>			
Deck .....	7540230		6755BR
Drive .....	7540245		6859
Transaxle .....	7540255		6837
<b>130-796</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>131-412</b>			
Blade .....	7540138	3500	6950

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>OUR OWN HARDWARE - Continued</b>			
<b>131-412 - Continued</b>			
Trans .....	7540101		6517BR
<b>131-452; 131-453</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>131-480; 131-490</b>			
Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
<b>132-380</b>			
Blade .....	7540138	3500	6950
Trans .....	7540164	2630	6863
<b>132-425; 132-435</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>132-480; 132-485</b>			
Blade .....	7540151		6957
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>133-420</b>			
Blade .....	7540147	3520	6952
Trans .....	7540136		6931
Variable Speed .....	7540135		6925
<b>133-440</b>			
Blade .....	7540178	3820	6982
Trans .....	7540179		6950
<b>133-470</b>			
Blade .....	7540151		6967
Trans .....	7540127		6966
<b>133-495</b>			
Blade .....	7540145		6488BR
Drive .....	7540127		6966
<b>134-390; 134-395</b>			
Drive .....	7540164	2630	6863
<b>134-402</b>			
Blade .....	7540188		6951
Drive; W/31" Belt O.C. ....	7540136		6931
<b>134-430</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>134-455; 134-465</b>			
Blade .....	7540178	3820	6982
Drive .....	7540185		6849
<b>134-504</b>			
Eng. To Deck .....	7540264		6639BR
Primary Variator .....	7540241		6494BR
Secondary Variator .....	7540240		6511BR
<b>134-698</b>			
Blade .....	7540145		6488BR
Trans .....	7540266		6775BR
<b>135-390; 135-395</b>			
Blade .....	7540167		6964
Trans .....	7540198		6451BR
<b>135-402</b>			
Blade .....	7540188		6951
Drive; W/31" Belt O.C. ....	7540136		6931
<b>135-430</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>135-445</b>			
Blade .....	7540200		6848
Trans .....	7540178	3820	6982

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>OUR OWN HARDWARE - Continued</b>			
<b>135-465</b>			
Blade .....	7540151		6957
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>135-497</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>136-390</b>			
Blade .....	7540167		6964
Trans .....	7540198		6451BR
<b>136-435</b>			
Blade .....	7540127		6966
Drive; W/25" Belt O.C. ....	7540135		6925
Drive; W/31" Belt O.C. ....	7540136		6931
<b>136-497</b>			
Blade .....	7540145		6488BR
Drive; W/37" Belt O.C. ....	7540173	3370	6937
Drive; W/65" Belt O.C. ....	7540191		6865
<b>136-525</b>			
Blade .....	7540195		6854
Trans .....	7540198		6451BR
<b>138-465</b>			
Blade .....	7540151		6957
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>138-497</b>			
Blade .....	7540145		6488BR
Transaxle .....	7540226		6551BR
<b>138-796</b>			
Blade .....	7540198		6451BR
Transaxle .....	7540207		6842
<b>140-660</b>			
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>140-960</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>144-660</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>144-860</b>			
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>144-990</b>			
P.T.O. ....	7540165		6834
<b>145-672</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>145-834</b>			
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540244		6840
<b>145-990</b>			
Gen. ....	7540169	7355	
P.T.O. ....	7540165		6834
<b>146-760</b>			
Trans. ....	7540182		6981
<b>146-834</b>			
Blade .....	7540293		6501BR
Deck .....	7540230		6755BR
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540244		6840
<b>146-990</b>			
Gen. ....	7540169	7355	



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>OUR OWN HARDWARE - Continued</b>			
<b>146-990 - Continued</b>			
P.T.O. ....	7540165		6834
<b>PANZER</b>			
<b>1107; 1110R</b>			
Trans. ....	74207	3340	6934
<b>T50; T60; T65; T70; T70B; T70BES; T75</b>			
Belt; W/34" Belt O.C. ....	T50167	3340	6934
<b>T102; T110; T115; T120; T205; T210; T215; T220</b>			
Belt; W/38" Belt O.C. ....	T10234	3380	6938
<b>T707ES; T707ESL; T758ES</b>			
Belt; W/34" Belt O.C. ....	T50167	3340	6934
<b>PENNEYS</b>			
<b>143-860; 143-960; 143-990</b>			
Clutch .....	7540124		6857
P.T.O. ....	7540165		6834
<b>144-672; 144-760</b>			
Gen. ....	7540134	7330	
<b>144-960; 144-990</b>			
Clutch .....	7540124		6857
P.T.O. ....	7540165		6834
<b>0274</b>			
Deck .....	7540342		6866
<b>1214</b>			
Clutch .....	7106		6822
Drive .....	7206		6829
<b>1400; 1401</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>1407; 1407B</b>			
Belt; W/25" Belt O.C. ....	8672B		6825
Belt; W/31" Belt O.C. ....	9407B		6831
<b>1408</b>			
Belt; W/25" Belt O.C. ....	8672B		6825
Belt; W/29" Belt O.C. ....	8671B		6829
<b>1409</b>			
Blade .....	20717		6856
Drive .....	20715		6837
<b>1409A; 1410</b>			
Blade .....	20717		6856
Drive .....	20716		6837
<b>1411; 1412</b>			
Blade .....	20556		6848
Cross Drive .....	20555		6841
Drive .....	20716		6837
<b>1414</b>			
Blade; W/50" Belt O.C. ....	7540138	3500	6950
Blade; W/64" Belt O.C. ....	7540167		6964
Drive .....	7540164	2630	6863
<b>1415; 1415A</b>			
Clutch .....	7106		6822
Drive .....	7206		6829
<b>1417; 1418; 1419; 1419A</b>			
Belt; W/25" Belt O.C. ....	8672B		6825
Belt; W/29" Belt O.C. ....	8671B		6829
<b>1421</b>			
Blade .....	7540151		6967
Drive .....	7540147	3520	6952
Trans. ....	7540136		6931
<b>1422</b>			
Blade .....	7540151		6967
Eng. To Pulley .....	7540138	3500	6950
Pulley To Trans. ....	7540136		6931
<b>1424</b>			
Blade; W/50" Belt O.C. ....	7540138	3500	6950

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PENNEYS - Continued</b>			
<b>1424 - Continued</b>			
Blade; W/64" Belt O.C. ....	7540167		6964
Drive .....	7540164	2630	6863
<b>1426</b>			
Belt; W/31" Belt O.C. ....	40591	2310	6831
Belt; W/44" Belt O.C. ....	41454	3440	6944
<b>1427</b>			
Blade .....	7540118		6963
Trans. ....	7540115	3610	6961
<b>1427A; 1427B; 1427C</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>1429</b>			
Blade .....	7540127		6966
Trans.; W/25" Belt O.C. ....	7540135		6925
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>1430</b>			
Blade .....	21058		6863
Cross Drive .....	21059		6844
Drive .....	20715		6837
<b>1430A</b>			
Blade .....	20558		6864
Cross Drive .....			6846
Drive .....	20716		6837
<b>1431</b>			
Blade .....	7540151		6967
Drive .....	7540147	3520	6952
Trans. ....	7540136		6931
<b>1432</b>			
Blade .....	7540145		6488BR
Eng. To Pulley .....	7540138	3500	6950
Pulley To Trans. ....	7540136		6931
<b>1433</b>			
Blade .....	20558		6864
Cross Drive .....			6846
Drive .....	20716		6837
<b>1434</b>			
Blade .....	7540113	3480	6948
Drive .....	754112	3800	6980
Gen. ....	7540134	7330	
<b>1435; 1435A</b>			
Blade .....	R310		6825
Drive .....	R240		6829
<b>1436</b>			
Belt; W/31" Belt O.C. ....	40591	2310	6831
Belt; W/44" Belt O.C. ....	41454	3440	6944
<b>1437; 1437A</b>			
Blade .....	7540113	3480	6948
Drive .....	754112	3800	6980
Gen. ....	7540134	7330	
<b>1439; 1439A</b>			
Blade .....	7540118		6963
Gen. ....	7540134	7330	
Trans. ....	7540937	3590	6959
<b>1440; 1440A</b>			
Blade .....	7540145		6488BR
Drive .....	7540147	3520	6952
Trans. ....	7540136		6931
<b>1447</b>			
Blade .....	7540113	3480	6948
Drive .....	754112	3800	6980
Gen. ....	7540134	7330	
<b>1448</b>			
Blade .....	7540113	3480	6948
Drive .....	754112	3800	6980
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PENNEYS - Continued</b>			
<b>1448A; 1448B</b>			
Blade .....	7540113	3480	6948
Drive .....	754112	3800	6980
Gen. ....	7540134	7330	
<b>1449</b>			
Blade .....	7540113	3480	6948
Drive .....	754112	3800	6980
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>1450</b>			
Blade; W/52" Belt O.C. ....	530050008		6952
Blade; W/57" Belt O.C. ....	530050009		6857
Main Drive .....	530050003		6851
<b>1459</b>			
Blade .....	7540127		6966
Drive .....	7540128		6935
<b>1760; 1770</b>			
Trans. ....	7540124	2570	6857
<b>1800</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Drive .....	7540182	3810	6981
Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>1801; 1801A</b>			
Drive .....	7540107		6830
Transaxle .....	7540936		6847
<b>1802; 1803</b>			
Blade; W/25" Deck .....	7540138	3500	6950
Drive .....	7540164	2630	6863
<b>1804</b>			
Blade .....	7540151		6967
Drive .....	7540138	3500	6950
Trans. ....	7540136		6931
<b>1805</b>			
Blade .....	7540145		6488BR
Drive .....	7540138	3500	6950
Trans. ....	7540136		6931
<b>1805T</b>			
Blade .....	7540151		6967
Drive .....	7540138	3500	6950
Trans. ....	7540136		6931
<b>1807</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>1808</b>			
Blade .....	7540145		6488BR
Trans. ....	7540173	3370	6937
<b>1809</b>			
Blade; W/100" Belt O.C. ....	7540181		7014BR
Blade; W/52" Belt O.C. ....	7540184		6852
Deck .....			6954
Drive .....	7540182	3810	6981
Trans. ....	7540180		6510BR
<b>1810</b>			
Blade; W/100" Belt O.C. ....	7540181		7014BR
Blade; W/52" Belt O.C. ....	7540184		6852
Deck .....			6954
Drive .....	7540182	3810	6981
Trans.; W/54" Belt O.C. ....	7540180		6510BR
Trans.; W/81" Belt O.C. ....	7540182	3810	6981
<b>1812</b>			
Blade; W/25" Deck .....	7540138	3500	6950
Drive .....	7540164	2630	6863
<b>1814; 1814T</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>1815</b>			
Blade .....	21649		6449BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PENNEYS - Continued</b>			
<b>1815 - Continued</b>			
Cross Drive .....	21059		6844
Drive .....	21615		6895
<b>1817</b>			
Drive .....	7540182	3810	6981
<b>1818</b>			
Blade .....	7540151		6967
Trans. ....	7540127		6966
<b>1819</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>1820A; 1820B</b>			
Blade .....	7540195		6854
Drive .....	7540198		6451BR
<b>1821; 1822</b>			
Blade .....	21649		6449BR
Drive .....	21615		6895
<b>1823; 1823A</b>			
Deck .....	7540180		6510BR
Trans. ....	7540182	3810	6981
<b>1824; 1824A</b>			
Blade .....	21649		6449BR
Drive .....	21615		6895
<b>1825; 1825A</b>			
Cross Deck .....	23749		6899
Drive .....	23072		6843
Right Angle Drive .....	23098		6793BR
<b>1827; 1827A; 1828; 1828A</b>			
Blade .....	7540145		6488BR
Drive .....	7540173	3370	6937
Trans. ....	7540191		6865
<b>1829</b>			
Blade .....	23214		6859
Cross Drive .....	23223		6895
Drive .....	21615		6895
<b>1830</b>			
Clutch; W/34" Belt O.C. ....	174883		6834
Drive .....	174224		6866
Eng. To Deck .....	176439		6424BR
Gen. ....	157524	7390	
Spindle .....	108209		6415BR
Trans.; W/53" Belt O.C. ....			6853
<b>1831</b>			
Blade .....	7540195		6854
Drive .....	7540198		6451BR
<b>1832</b>			
Blade .....	7540107		6830
Drive .....			6847
Trans. ....	7540936		6847
<b>1833</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>1834</b>			
Cross Drive .....	23749		6899
Drive .....	21615		6895
<b>1835</b>			
Transaxle .....	7540226		6551BR
<b>1839</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>1841; 1842</b>			
Blade .....	23882		A57
Cross Drive .....			6846
Drive .....	23347		6882
<b>1844</b>			
J.S. ....	7540245		6859
Trans. ....	7540244		6840



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PENNEYS - Continued</b>			
<b>1845; 1846</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>1851; 1851A</b>			
P.T.O. ....	7540165		6834
<b>1852</b>			
Belt; W/42" Deck .....	7540125		6428BR
Drive .....	7540124		6857
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540169	7355	
<b>1853; 1853A</b>			
Belt; W/42" Deck .....	7540125		6428BR
Belt; W/52" Deck .....	7540197		6604BR
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540169	7355	
<b>1854</b>			
J.S. ....	7540245		6859
Trans. ....	7540243		6846
<b>1855</b>			
Belt; W/45" Belt O.C. ....	7540212		6945
Belt; W/50" Belt O.C. ....	7540214		6850
Belt; W/63" Belt O.C. ....	7540227		6963
<b>1856</b>			
Drive .....	23098		6793BR
Right Angle Drive .....	23853		A41
<b>1857</b>			
Blade .....	7540230		6755BR
Drive .....	7540245		6859
J.S. ....	7540245		6859
Transaxle .....	7540244		6840
<b>1858</b>			
Deck; W/Optional 44" Deck .....	7540230		6755BR
Drive .....	7540245		6859
Transaxle .....	7540255		6837
<b>1861</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>1863</b>			
Blade .....	7540279		6965
Trans. ....	7540198		6451BR
<b>1865</b>			
Blade .....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>1880</b>			
J.S. ....	7540245		6859
Trans. ....	7540244		6840
<b>1900</b>			
Blade .....	20717		6856
Drive .....	20716		6837
<b>1901</b>			
Blade .....	20556		6848
Cross Drive .....	20555		6841
Drive .....	20716		6837
<b>1903</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540179		6950
<b>1904; 1905; 1905A; 1906; 1907; 1907A; 1909</b>			
Blade .....	20717		6856
Drive .....	20716		6837
<b>1910</b>			
Blade .....	21649		6449BR
Drive .....	20716		6837
<b>1960; 1970</b>			
Trans. ....	7540124	2570	6857
<b>3797</b>			
J.S. ....	7540245		6859
Trans. ....	7540244		6840

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PENNEYS - Continued</b>			
<b>5081</b>			
Deck .....	7540245		6859
Traction .....	7540177		6832
<b>5107</b>			
Variable Speed .....	7540245		6859
<b>8866</b>			
Traction .....	37X61		6452BR
<b>8867</b>			
Blade .....	37X57		6498BR
Traction .....	37X33		6890
<b>PENNSYLVANIA</b>			
<b>900; 900X</b>			
Blade .....	74254		6852
Trans. ....	74238	2440	6844
<b>906; 907R; 908X</b>			
Blade .....	74255	2860	6886
Trans. ....	74243	2340	6834
<b>71243-1; 71243A-1; 71243B-1; 71243C; 71243D; 71243E</b>			
Rotary .....	7181		6836
<b>PENN 88A; PENN 88AES; PENN 88ES</b>			
Belt; W/33" Belt O.C. ....	74203		6833
<b>POLORON</b>			
<b>323</b>			
Blade .....	107364		6957
Trans. ....	107111		6942
<b>383</b>			
Blade .....	106709		6975
Trans. ....	116462		6863
Transaxle .....	116511		6894
<b>528; 630; 730</b>			
Blade .....	965503	2530	6853
Friction Drive .....	965500	2310	6831
<b>4400M; 4401M; 4402M</b>			
Blade .....	107604		6963
Trans. ....	107111		6942
<b>5401M; 5402M; 5402Z</b>			
Blade .....	106709		6975
Trans. ....	116462		6863
<b>5403M</b>			
Blade .....	106709		6975
<b>5404M; 5404Z</b>			
Blade .....	106709		6975
Trans. ....	116462		6863
<b>5500M; 5501M</b>			
Blade .....	116904		6963
Trans. ....	107111		6942
<b>6501M; 6502M</b>			
Blade .....	106709		6975
Trans. ....	116462		6863
<b>6503M</b>			
Blade .....	106709		6975
Transaxle .....	116511		6894
<b>6504M; 6504Z</b>			
Blade .....	106709		6975
Trans. ....	116462		6863
<b>6600M; 6601M</b>			
Blade .....	116904		6963
Trans. ....	107111		6942
<b>7601M</b>			
Blade .....	116991		6966
Trans. ....	107111		6942
<b>8602M</b>			
Blade .....	106709		6975
Trans. ....	116462		6863

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>POLORON - Continued</b>			
<b>8603M</b>			
Blade .....	106709		6975
Transaxle .....	116511		6894
<b>8604M</b>			
Blade .....	106709		6975
Trans. ....	116462		6863
<b>8605M</b>			
Blade .....	106709		6975
Transaxle .....	116511		6894
<b>8727</b>			
Blade .....	965504		6942
Friction Drive .....	965500		6831
<b>8728</b>			
Blade .....	965504	3420	6942
Trans. ....	965500	2310	6831
<b>8730; 8732</b>			
Blade .....	965504		6942
Friction Drive .....	965500		6831
Trans. ....	965500	2310	6831
<b>8902 Garden Pro</b>			
Belt .....	116462		6863
<b>8903 Garden Pro</b>			
Belt .....	117328		6463BR
<b>8904 Garden Pro</b>			
Belt .....	116462		6863
<b>8905 Garden Pro</b>			
Belt .....	117328		6463BR
<b>9702B; 9704B</b>			
Blade .....	106709		6975
Trans. ....	116462		6863
<b>9710 Stallion; 9730 Stallion; 9732 Stallion; 9740 Stallion; 9742 Stallion; 9832 Stallion; 9843 Stallion; 9844 Stallion</b>			
Blade .....	965507		6880
Deck; W/32" Deck .....	965504		6942
Deck; W/40" Deck .....	965508		6943
Transaxle .....	965500		6831
<b>9902 Garden Pro; 9903 Garden Pro; 9904 Garden Pro; 9905 Garden Pro</b>			
Belt .....	106709		6975
<b>10511; 10821 Stallion; 10822 Stallion</b>			
Blade .....	107112		6937
Trans. ....	107111		6942
<b>10831; 10832; 10833</b>			
Blade .....	965504	3420	6942
Trans. ....	965500	2310	6831
<b>11031J Fleetwood; 11033J Fleetwood; 12031J Cougar; 12033J Cougar</b>			
Blade .....	107364		6957
Trans. ....	107111		6942
<b>12831 Stallion</b>			
Blade .....	965504	3420	6942
Trans. ....	965500	2310	6831
<b>13031J Stallion</b>			
Blade .....	107364		6957
Trans. ....	107111		6942
<b>18728; 18730; 18732</b>			
Blade .....	965504	3420	6942
Trans. ....	965500	2310	6831
<b>19710 Fleetwood; 19730 Fleetwood; 19740 Fleetwood; 19742 Fleetwood; 19750 Fleetwood; 19752 Fleetwood; 19832 Fleetwood; 19834 Fleetwood; 19844 Fleetwood</b>			
Deck; W/32" Deck .....	965504	3420	6942
Deck; W/40" Deck; W/43" Belt O.C. ....	965508	3430	6943
Deck; W/40" Deck; W/80" Belt O.C. ....	965507	2800	6880
Trans. ....	965500	2310	6831

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>POLORON - Continued</b>			
<b>20511; 20821 Fleetwood; 20822 Fleetwood</b>			
Blade .....	107112		6937
Trans. ....	107111		6942
<b>20831 Fleetwood; 20832 Fleetwood; 20833 Fleetwood</b>			
Blade .....	965504	3420	6942
Trans. ....	965500	2310	6831
<b>21821 Jaguar</b>			
Blade .....	107112		6937
Trans. ....	107111		6942
<b>21831 Cougar; 21833 Cougar</b>			
Blade .....	965504	3420	6942
Trans. ....	965500	2310	6831
<b>30041J Fleetwood; 30043J Fleetwood</b>			
Blade .....	106709		6975
Drive .....	116176		6859
<b>30511 Mark III</b>			
Blade .....	107112		6937
Trans. ....	107111		6942
<b>32041J Cougar; 32043J Cougar; 40041J Fleetwood; 40043J Fleetwood; 40141J Fleetwood; 40143J Fleetwood; 43043J Stallion</b>			
Blade .....	106709		6975
Drive .....	116176		6859
<b>77418</b>			
Blade .....	965503	2530	6853
<b>POULAN PRO</b>			
<b>301ZX</b>			
Deck Drive .....	574173002		68100
Hydro. Drive .....	539120806		7026BR
<b>380ZX</b>			
Hydro. Drive .....	575852401		7027BR
<b>460ZX; 461ZX</b>			
Deck Drive .....	539117245		6589BR
Hydro. Drive .....	539110411		6755BR
<b>540ZX; 541ZX</b>			
Deck Drive .....	539114557		6597BR
Hydro. Drive .....	539110411		6755BR
<b>925ZX</b>			
Deck Drive .....	539109243		6785BR
Hydro. Drive .....	539110411		6755BR
<b>950ZX</b>			
Deck Drive .....	539110832		6759BR
Hydro. Drive .....	539110411		6755BR
<b>PB22H46YT</b>			
Deck Drive .....	405143		6821BR
Drive .....	130969		6457BR
<b>PB22H54BF</b>			
Deck Drive .....	196103		6767BR
Drive .....	130969		6457BR
<b>PB23H48YT</b>			
Deck Drive .....	197242		6786BR
Drive .....	130969		6457BR
<b>PB26H54YT</b>			
Deck Drive .....	196103		6767BR
Drive .....	130969		6457BR
<b>PB195H42LT</b>			
Deck Drive; 2009 & Older .....	197253		7015BR
Deck Drive; 2010 .....	532429636		6653BR
Drive; 2009 & Older .....	140218		6811BR
Drive; 2010 .....	532130969		6757BR
<b>PB195H46YT</b>			
Deck Drive .....	405143		6821BR
Drive .....	130969		6457BR
<b>PB2042YT</b>			
Deck Drive .....	429636		6653BR



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>POULAN PRO - Continued</b>				<b>PROFESSIONAL HARDWARE</b>			
<b>PB2042YT - Continued</b>				<b>136-504</b>			
Drive	194346		6765BR	Deck; W/30" Deck	7540264		6639BR
<b>PB19546LT</b>				Eng. To Variator; W/30" Deck	7540241		6494BR
Deck Drive	405143		6821BR	Variator To Trans.; W/30" Deck	7540240		6511BR
Drive	194346		6765BR	<b>136-668; 136-678</b>			
<b>PBGT26H54</b>				Deck	7540145		6488BR
Deck Drive	196103		6767BR	Eng. To V.S.	7540280		6447BR
Drive	125907X		6713BR	Transaxle	7540266		6775BR
<b>PO12530LT</b>				V.S. To Trans.	7540281		6405BR
Deck Drive	419271		6463BR	<b>138-370; 138-390</b>			
Drive	138255		6758BR	Blade	7540935		6831
<b>PO16542LT; PO17542LT; PO18542LT</b>				Transaxle	7540111		6845
Deck Drive	144959		6758BR	<b>809-6</b>			
Drive	138255		6758BR	Belt	754107		6830
<b>POWER EQUIPMENT</b>				<b>810-5; 810-6; 810-7; 810-8</b>			
<b>134-668</b>				Blade	754935	2310	6831
Blade	7540145		6488BR	Trans.	754936		6847
<b>144-824</b>				<b>847-8</b>			
Deck	7540230		6755BR	Blade	7540118		6963
J.S.	7540245		6859	<b>848-8; 884-7; 890-7</b>			
Transaxle	7540244		6840	Transaxle	7540112		6980
<b>POWER KING</b>				<b>891-7; 891-8</b>			
<b>1200 Series</b>				Blade	7540935		6831
Belt; 1983 & Newer	810089		6889	Transaxle	7540111		6845
Belt; Ser. No. 21299 & Before	810000		6831	<b>8230</b>			
Belt; Ser. No. 21300 & After	810025		6825	Blade	7540107		6830
Belt; W/29" Belt O.C.	810029		6829	Transaxle	7540936		6847
Cross Deck; W/42" Deck	810087		6887	<b>8230-4; 8230-5</b>			
Snow Thrower Attachment; 1983 & Newer; W/42" Auger	810070		6870	Blade	754188		6951
<b>Jim Dandy</b>				Drive	754164	2630	6863
Cross Deck; 1979 & Older; W/60" Deck	810052		6852	<b>8231-1</b>			
Deck; Ser. No. 21299 & Before	810000		6831	Blade	7540147		6952
Deck; Ser. No. 21300 & After	810025		6825	Variator To Trans.	7540136		6931
Snow Thrower Attachment; 1979-1974; W/42" Auger	810070		6870	<b>8231-2; 8231-3</b>			
Tiller Attachment; 1974 & Newer	810048		6848	Blade	754138	3500	6950
Traction; 1979-1974; W/48", 60" Deck	810080		6880	Trans.	754101		6517BR
Traction; W/Parallel Hitch; 1980 & Newer; W/48" Deck	810085		6885	<b>8232-1; 8232-2; 8232-3; 8232-4; 8233-1; 8233-2</b>			
Traction; W/Std. Hitch; 1980 & Newer; W/48" Deck	810080		6880	Deck	754127		6966
<b>Power King</b>				Drive	754135		6925
Cross Deck; 1979 & Older; W/60" Deck	810052		6852	Trans.	754136		6931
Deck; Ser. No. 21299 & Before	810000		6831	<b>8233-9</b>			
Deck; Ser. No. 21300 & After	810025		6825	Blade	7540138		6950
Snow Thrower Attachment; 1974; W/42" Auger	810072		6872	Transaxle	7540101		6517BR
Snow Thrower Attachment; 1979-1975; W/42" Auger	810094		6894	<b>8234-0</b>			
Tiller Attachment; 1974 & Newer	810052		6852	Blade	7540147		6952
Traction; W/16" Wheels; 1979-1974; W/48", 60" Deck	810085		6885	Variator To Trans.	7540136		6931
Traction; W/16" Wheels; 1980 & Newer; W/48" Deck	810085		6885	<b>8234-3</b>			
Traction; W/16" Wheels; 1980 & Newer; W/60" Deck	810087		6887	Blade	7540178		6982
Traction; W/24" Wheels; 1979-1974; W/48", 60" Deck	810092		6892	Transaxle	7540179		6950
Traction; W/24" Wheels; 1980 & Newer; W/60" Deck	810089		6889	<b>8234-4</b>			
Traction; W/24" Wheels; W/Std. Hitch; 1979-1974; W/48" Deck	810087		6887	Blade	754175	3820	6982
<b>Power King 1218HV</b>				Drive	754178	3820	6982
Blade	810094		6894	<b>8234-5; 8234-6</b>			
P.T.O.			6867	Blade	7540178		6982
<b>Power King 1618</b>				Transaxle	7540200		6848
P.T.O.	810089		6889	<b>8235-0</b>			
<b>Power King 1620HV</b>				Deck	754127		6966
P.T.O.	102224		6844	Drive	754135		6925
				Trans.	754136		6931
				<b>8236-0</b>			
				Blade	7540107		6830
				Transaxle	7540111		6845
				<b>8236-9</b>			
				Blade	7540105		6830
				Transaxle	7540111		6845

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PROFESSIONAL HARDWARE - Continued</b>			
8237-1; 8237-2; 8237-3; 8237-4; 8237-5; 8237-6; 8237-7; 8237-8			
Blade .....	754107		6830
Trans. ....	754936		6847
8239-2			
Blade; W/25" Deck .....	7540138		6950
Blade; W/30" Deck .....	7540167		6964
Transaxle .....	7540164		6863
8239-3			
Blade .....	754138	3500	6950
Trans. ....	754164	2630	6863
8240-6			
Blade .....	7540151		6967
Variator To Trans. ....	7540136		6931
8240-7; 8240-8			
Drive .....	754138	3500	6950
Trans. ....	754136		6931
8241-1			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540147		6952
Variator To Trans. ....	7540136		6931
8241-2; 8241-3; 8241-4; 8241-5			
Drive .....	754138	3500	6950
Trans. ....	754136		6931
8242-0			
Blade .....	7540118		6963
Transaxle .....	7540937		6959
8242-3; 8242-4			
Drive .....	754127		6966
8242-5			
Blade .....	7540151		6967
Transaxle .....	7540191		6865
8242-9			
Blade .....	7540118		6963
Starter/Gen. ....	7540134		6733
Transaxle .....	7540937		6959
8243-0			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540147		6952
Variator To Trans. ....	7540136		6931
8243-2			
Blade .....	754145	3500	6488BR
Drive .....	754138		6950
Trans. ....	754136		6931
8244-6; 8244-7			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540191		6865
Variator To Trans. ....	7540173		6937
8244-8			
Blade .....	7540145		6488BR
Transaxle .....	7540226		6551BR
8245-0; 8245-1; 8245-2			
Gen. ....	7540134		6733
Trans. ....	754112	3800	6980
8245-3			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Gen. ....	7540134		6733
Trans. ....	7540182	3810	6981
8245-9			
Gen. ....	7540134		6733
Trans. ....	754112	3800	6980
8246-0; 8246-1; 8246-2			
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
8246-4; 8246-5			
Blade .....	7540184		6852

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PROFESSIONAL HARDWARE - Continued</b>			
8246-4; 8246-5 - Continued			
Deck .....	7540180		6510BR
Gen. ....	7540134		6733
Trans. ....	7540182	3810	6981
8337-2			
Blade .....	754107		6830
Trans. ....	754936		6847
<b>RANSOMES, INC.</b>			
185 T-Plex			
Fan & Alt. ....		7345	
250			
Fan & Alt.; W/23, 28 H.P. Eng. ....		7375	
723D; 728D			
Fan & Alt. ....		7375	
3500 Kubota Diesel			
Fan & Alt. ....	REMF6420	9430	9430HD
<b>REDMAX</b>			
CZT48x			
Hydro. Drive .....	573978301		6675BR
CZT52			
Deck Drive .....	522811301		6692BR
Hydro. Drive .....	574870901		7007BR
CZT54x			
Hydro. Drive .....	573978301		6675BR
CZT60x			
Deck Drive .....	588264801		6938BR
Hydro. Drive .....	573978301		6675BR
RZT42; RZT48			
Hydro. Drive .....	539110411		6755BR
RZT48x			
Hydro. Drive .....	574870901		7007BR
RZT54			
Hydro. Drive .....	539110411		6755BR
RZT54x			
Hydro. Drive .....	574870901		7007BR
RZT61x			
Deck Drive .....	539104335		6760BR
Hydro. Drive .....	574870901		7007BR
YT1846			
Deck Drive .....	532405143		6821BR
Drive .....	532130969		6757BR
YT2142F; YT2348F			
Drive .....	532130969		6757BR
<b>REO</b>			
2-1231; 2-2231			
Blade .....	1596		6851
Eng. To Trans. ....	1597		6725
Mower Clutch .....	6993		6822
Trans. To Cam. ....	1597		6725
426AE; 426R; 426RE			
Belt .....	MW6953	2350	6835
600; 725			
Belt .....	15294	3430	6943
RE65			
Blade .....	1596		6851
Drive .....	1597		6725
Spindle .....	1598		6822
RE66; RE67			
Blade .....	1596		6851
Drive .....	1597		6725
Mower Clutch .....	6993		6822
Spindle .....	1598		6822
Trans. To Cam. ....	1597		6725





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>REO - Continued</b>			
<b>RR46; RR47; RR65</b>			
Blade .....	1596		6851
Drive .....	1597		6725
Spindle .....	1598		6822
<b>RR66; RR67</b>			
Blade .....	1596		6851
Drive .....	1597		6725
Mower Clutch .....	6993		6822
Spindle .....	1598		6822
Trans. To Cam .....	1597		6725
<b>ROOT</b>			
<b>630</b>			
Blade .....	428	3720	6972
Trans. ....	431		6834
<b>Lariat</b>			
Blade .....	426		6856
Trans. ....	512		6829
<b>Palomino 60</b>			
Belt .....	1351		6957
Eng. To Deck .....	1350		6999
<b>RD; RR24; RR26</b>			
Blade .....	430		6962
Traction .....	431		6834
<b>ROOT</b>			
<b>1030; Pathfinder 726; Pathfinder 730; Pathfinder 830; Pathfinder 830-E</b>			
Blade Drive .....	7421		6866
Eng. To Countershaft .....	8809		6836
Eng. To Transaxle .....	8810		6837
<b>Zip 245</b>			
Drive .....	70034	2410	6841
Mower Drive .....	70052	2440	6844
<b>ROPER</b>			
<b>1A1A1A; 1D2A3A; 1E2A9A</b>			
Drive .....	124525X		6889
<b>1H2A9A</b>			
Deck .....	131290		6459BR
Ground Drive .....	126520X		6459BR
<b>1H2A9B</b>			
Drive .....	126520X		6459BR
<b>2E3B3A</b>			
Drive .....	125907X		6713BR
<b>6A1A1A; 6B1A1A; 6D1A9A; 6H2A9A</b>			
Drive .....	124525X		6889
<b>7D3B3A</b>			
Drive .....	125907X		6713BR
<b>810</b>			
Deck .....	305698		6873
<b>3363-14</b>			
Drive .....	126520X		6459BR
P.T.O. ....	124293X		6880
<b>3364-14</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>3380-14</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>3383-14</b>			
Deck .....	125907X		6713BR
Ground Drive .....	125907X		6713BR
<b>4180-14; 4180-24; 4180-24B; 4180-34</b>			
Deck .....	106085X		6672BR
Ground Drive .....	123796X		6432BR
<b>4200-14; 4200-34</b>			
Blade .....	3703J		68100

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>4200-14; 4200-34 - Continued</b>			
Drive .....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>601020</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>601200</b>			
Blade .....	108597X		6457BR
Drive .....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>601320</b>			
Blade .....	126576		6820
<b>601480</b>			
Blade .....	125908X		6893
<b>601520; 602020; 602021</b>			
Blade .....	125907X		6713BR
<b>602200</b>			
Blade .....	3703J		68100
Drive .....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>602220; 602221</b>			
Blade .....	125907X		6713BR
<b>602280; 602281; 602282</b>			
Blade .....	123796X		6432BR
<b>602420</b>			
Drive .....	602420		6890
<b>607110</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>607240</b>			
Blade .....	125907X		6713BR
<b>607280; 607281</b>			
Blade .....	123796X		6432BR
<b>609422</b>			
Blade .....	125907X		6713BR
<b>951940</b>			
Blade .....	3703J		68100
Drive .....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>AN12R38A; AN1236A</b>			
Drive .....	124525X		6889
<b>AYP122B29; AYP7122A39</b>			
Blade .....	125907X		6713BR
<b>AYP8186A29</b>			
Deck .....	106085X		6672BR
Ground Drive .....	123796X		6432BR
<b>AYP8186A39; AYP8186B39</b>			
Blade .....	123796X		6432BR
<b>AYP8208A29; AYP8208A39; AYP8208B39</b>			
Blade .....	3703J		68100
Drive .....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>AYP9128A39; AYP9128B29</b>			
Blade .....	123796X		6432BR
<b>B1236D; BL2T36B; BL12R38A; BL12T36A</b>			
Drive .....	126520X		6459BR
<b>BL16H44C</b>			
Blade .....	123461X		6881
<b>BL125H38B; BL125H38C</b>			
Blade .....	126576X		6882
<b>BL1236A</b>			
Drive .....	126520X		6459BR
<b>BL1238C; BL1238E</b>			
Blade .....	125907X		6713BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>BL1844B</b>			
Blade .....	123796X		6432BR
<b>BNGT180AE; BNGT1850AE</b>			
Blade .....	3703J	68100	
Drive .....	110883X	6899	
P.T.O. ....	110884X	6714BR	
<b>BNLT120BE; BNRLT1238AE</b>			
Blade .....	125907X	6713BR	
<b>BNYTH1644AE</b>			
Blade .....	123461X	6881	
<b>CC1236A</b>			
Drive .....	124525X	6889	
P.T.O. ....	124293X	6880	
<b>CM2050A</b>			
Blade .....	3703J	68100	
Drive .....	110883X	6899	
P.T.O. ....	110884X	6714BR	
<b>CP1036A; CP1036B</b>			
Drive .....	124525X	6889	
<b>CP2050A</b>			
Blade .....	3703J	68100	
Drive .....	110883X	6899	
P.T.O. ....	110884X	6714BR	
<b>CT10L36A; CT10L36B</b>			
Drive .....	124525X	6889	
<b>CT125R38A</b>			
Deck .....	131290	6459BR	
Ground Drive .....	126520X	6459BR	
<b>CT125R38B</b>			
Drive .....	124525X	6889	
<b>CT1036A</b>			
Drive .....	124525X	6889	
P.T.O. ....	124293X	6880	
<b>CT1138A</b>			
Deck .....	106085X	6672BR	
Ground Drive .....	125907X	6713BR	
<b>CT1138B; CT1138C</b>			
Blade .....	125907X	6713BR	
<b>CT1236A; CT1236B</b>			
Drive .....	124525X	6889	
P.T.O. ....	124293X	6880	
<b>CT1238A; CT1538A</b>			
Blade .....	125907X	6713BR	
<b>CT1844B; CT1844C; CT1844E</b>			
Deck .....	106085X	6672BR	
Drive .....	123554X	6894	
<b>CT2050A</b>			
Blade .....	3703J	68100	
Drive .....	110883X	6899	
P.T.O. ....	110884X	6714BR	
<b>CT12538B</b>			
Blade .....	125907X	6713BR	
<b>EN12R38A</b>			
Drive .....	124525X	6889	
<b>F836D</b>			
Drive .....	126520X	6459BR	
<b>F1036C</b>			
Drive .....	126520X	6459BR	
P.T.O. ....	124293X	6880	
<b>F1036D</b>			
Drive .....	126520X	6459BR	
<b>F1236C</b>			
Drive .....	126520X	6459BR	
P.T.O. ....	124293X	6880	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>F1236D; FA125R38A; FA125R388; FA10536A</b>			
Drive .....	126520X		6459BR
<b>FMLR1036AE</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>FMLR1236AE</b>			
Drive .....	126520X		6459BR
P.T.O. ....	124293X		6880
<b>FMLT120AE</b>			
Blade .....	125907X		6713BR
<b>G1236</b>			
Drive .....	124525X		6889
<b>G1238A; GM12538A; GM12538E</b>			
Blade .....	125907X		6713BR
<b>GP1036A; GP1036B; GP1236A</b>			
Drive .....	124525X		6889
<b>GT2500AR</b>			
Deck .....	106085X		6672BR
Drive .....	123554X		6894
<b>H14H38B; H14H44A; H125H38A</b>			
Blade .....	123461X		6881
<b>H1036A; H1036B; H1036C; H1036D</b>			
Drive .....	126520X		6459BR
<b>H1236A</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>H1236B; H1236D</b>			
Drive .....	126520X		6459BR
<b>H1338B</b>			
Blade .....	125907X		6713BR
<b>H1644C</b>			
Blade .....	123796X		6432BR
<b>H12536A</b>			
Drive .....	126520X		6459BR
<b>H12538D</b>			
Blade .....	125907X		6713BR
<b>HA125R38A; HA125R38B</b>			
Drive .....	126520X		6459BR
<b>HA1036A; HA1036B</b>			
Drive .....	126520X		6459BR
P.T.O. ....	124293X		6880
<b>Halt120Ae</b>			
Blade .....	125907X		6713BR
<b>HU125R38MA</b>			
Drive .....	126520X		6459BR
<b>HU1036A</b>			
Drive .....	124525X		6889
<b>HU1236A; HU1236B; HU1236C</b>			
Drive .....	126520X		6459BR
<b>HVLT10AE; HVLT125AE</b>			
Blade .....	125907X		6713BR
<b>HVYTH140AR; HVYTH141AR</b>			
Blade .....	123461X		6881
<b>J8L36A</b>			
Drive .....	126520X		6459BR
<b>J12H38B</b>			
Blade .....	123461X		6881
<b>J125R38A; J125R38B; J1036A; J1036B; J1036C; J1236B; J1236C; J1236D</b>			
Drive .....	126520X		6459BR
<b>JLH238AE</b>			
Blade .....	125907X		6713BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>JLR836AE; JLR1136AE</b>			
Drive .....	126520X		6459BR
P.T.O. ....	124293X		6880
<b>K824; K922</b>			
Belt .....	67346		6839
<b>K932</b>			
Blade .....	67398		6853
Trans. ....	67346		6839
<b>K8241AR</b>			
Blade, W/Single Deck .....	74164		6851
Trans. ....	67348		6847
<b>K8327AR; K8327BR; K8327CR</b>			
Blade .....	67398		6853
Eng. To Deck .....	74212		6857
Trans. ....	67346		6839
<b>K43046R</b>			
Belt .....	67346		6839
<b>K51136R; K52136R; K52236R</b>			
Blade .....	67438		6847
Trans. ....	67346		6839
<b>K83136R; K83236R</b>			
Blade .....	67398		6853
Trans. ....	67346		6839
<b>L077; L081</b>			
Eng. To Deck .....	100717N		6869
<b>L190</b>			
Deck .....	62828		6870
<b>L219AR; L219BR</b>			
Deck .....	62828		6870
Trans. ....	73794		6894
<b>L0232AR</b>			
Blade .....	518J		6869
<b>L0238AR; L0239AR</b>			
Deck .....	62828		6870
Trans. ....	73794		6894
<b>L250</b>			
Spindle; W/44" Deck; W/18 H.P. Eng. ....	106085		6879
<b>L0262AR</b>			
Blade .....	518J		6869
<b>L1252</b>			
Deck .....	62828		6870
<b>L1900BR</b>			
Deck .....	62828		6870
Eng. To Deck; W/36" Deck .....	62828		6870
Eng. To Transaxle .....	121979X		6463BR
<b>L2950AR</b>			
Blade .....	125907X		6713BR
<b>L06356R1</b>			
Trans. ....	71240		A90
<b>L8112</b>			
Blade .....	518J		6869
<b>L8217AR; L8218BR; L8218CR; L8218DR</b>			
Deck .....	62828		6870
Trans. ....	73794		6894
<b>L71136R; L71136R1; L72146R; L72146R1; L72256R</b>			
Blade .....	70637		6840
Trans. ....	58406		6865
<b>L82146</b>			
J.S. ....	62828		6870
Transaxle .....	71240		A90
<b>L82146R</b>			
Trans. ....	71240		A90

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>L86156</b>			
J.S. ....	62828		6870
Transaxle .....	71240		A90
<b>L86156R1</b>			
Deck .....	62828		6870
Trans. ....	71240		A90
<b>L86356</b>			
J.S. ....	62828		6870
Transaxle .....	71240		A90
<b>L86356R</b>			
Trans. ....	71240		A90
<b>LM1236A</b>			
Drive .....	124525X		6889
<b>LO6356R1</b>			
J.S. ....	62828		6870
Transaxle .....	71240		A90
<b>LT10</b>			
Deck .....	62828		6870
Trans. ....	73794		6894
<b>LT11</b>			
Deck .....	62828		6870
Spindle; W/44" Deck .....	106085		6879
Trans. ....	73794		6894
<b>LT14; LT16</b>			
Spindle; W/44" Deck .....	106085		6879
<b>LT110CR</b>			
Deck .....	106085X		6672BR
Drive .....	130969		6457BR
<b>LT110</b>			
Eng. To Deck .....	100670N		6879
Trans. ....	105380X		6463BR
<b>LT1219AR</b>			
Deck .....	62828		6870
Trans. ....	73794		6894
<b>M12R38A; MD1236A</b>			
Drive .....	124525X		6889
<b>MD12538A; N1038AE</b>			
Blade .....	125907X		6713BR
<b>N1192A</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>N1236A; N1236B</b>			
Drive .....	124525X		6889
<b>N1238AE; N1238B; N1296A; N12538A</b>			
Blade .....	125907X		6713BR
<b>NN10L36A; NN12R38A; OB12R38A; OB12R38B</b>			
Drive .....	124525X		6889
<b>OB1138AE; OB1238AE; OB12538AE; OB12538B; OB12538C</b>			
Blade .....	125907X		6713BR
<b>P8L90D; P8L90E</b>			
Drive .....	126520X		6459BR
<b>P16H115C</b>			
Blade .....	123461X		6881
<b>P890B; P1090B</b>			
Drive .....	126520X		6459BR
P.T.O. ....	124293X		6880
<b>P1090D; P1090E</b>			
Drive .....	126520X		6459BR
<b>P1290B</b>			
Drive .....	126520X		6459BR
P.T.O. ....	124293X		6880
<b>P1290D</b>			
Drive .....	126520X		6459BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>P1295C; P1295E</b>			
Blade .....	125907X		6713BR
<b>PALR100AE; PALR120AE</b>			
Drive .....	126520X		6459BR
P.T.O. ....	124293X		6880
<b>PALT120AE</b>			
Blade .....	125907X		6713BR
<b>PALTH160AE</b>			
Blade .....	123461X		6881
<b>PC1844A</b>			
Deck .....	106085X		6672BR
Drive .....	123554X		6894
<b>PP12R38MA</b>			
Drive .....	124525X		6889
<b>PP14H44A; PP16H44A; PP16H44B; PP16H44C; PP125H38A; PP125H38B</b>			
Blade .....	123461X		6881
<b>PP1036SA; PP1136A</b>			
Drive .....	124525X		6889
<b>PP1236A</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>PP1844B</b>			
Blade .....	123796X		6432BR
<b>PP12538B</b>			
Blade .....	125907X		6713BR
<b>PT1236A; PT1236B</b>			
Drive .....	124525X		6889
<b>RC12326B</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>RE10L36B; RE10M36A; RE12R38A</b>			
Drive .....	124525X		6889
<b>RE1038B; RE1238B; RE1238C</b>			
Blade .....	125907X		6713BR
<b>RL10L36A; RL10L36B</b>			
Drive .....	124525X		6889
<b>RL12N38A</b>			
Blade .....	125907X		6713BR
<b>RL12R38A</b>			
Drive .....	124525X		6889
<b>RL12T38B; RL1036AR; RL1036B</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>RL1038AE</b>			
Drive .....	125907X		6713BR
P.T.O. ....	106085		6879
<b>RL1136A</b>			
Drive .....	124525X		6889
<b>RL1236A</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>RL1238AR</b>			
Blade .....	125907X		6713BR
<b>RL1238C</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>RL1238D; RL1442B</b>			
Blade .....	125907X		6713BR
<b>RL1844AE; RL1844AR</b>			
Blade .....	125908X		6893
<b>RL1844B</b>			
Deck .....	106085X		6672BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>RL1844B - Continued</b>			
Drive .....	125908X		6893
<b>RLT10L36A; RLT12R38A; RLT125R38A; RLT125R38B</b>			
Drive .....	124525X		6889
<b>RLTE1238AR; RR1138B; RR1238B</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>S12R38B; SB125R38A</b>			
Drive .....	124525X		6889
<b>SC1138AE</b>			
Blade .....	125907X		6713BR
<b>SC1236A</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>SC1238AE; SK128A; SK1238B; SK1238C; SK1238D; SK1238E</b>			
Blade .....	125907X		6713BR
<b>T1136A</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>T1136B</b>			
Drive .....	124525X		6889
<b>T1228AR; T1228BR; T1228CR; T1228DR; T1228ER</b>			
Drive .....	8845R		6874
<b>T1238B</b>			
Deck .....	106085X		6672BR
Ground Drive .....	125907X		6713BR
<b>T1238C; T1238D</b>			
Blade .....	125907X		6713BR
<b>T4328AR; T4328BR; T4328CR</b>			
Drive .....	8845R		6874
<b>T6328AR; T6328BR; T6328CR; T6328R; T8328AR; T8328BR</b>			
Trans. ....	2692R		6983
<b>T8338AR</b>			
Trans. ....	5125R		6868
<b>T9329AR; T9329BR; T9329DR; T9329ER</b>			
Trans. ....	2692R		6983
<b>T32231RO; T32241R1; T32241R2; T32241R3; T32241R4; T32241RO</b>			
Starter/Gen. ....	9766H	7355	
Transaxle .....	2295R		6982
<b>T32341RO</b>			
Transaxle .....	6095R		6866
<b>T51844A</b>			
Blade .....	123796X		6432BR
<b>T52050A</b>			
Blade .....	3703J		68100
Drive .....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>T62231RO</b>			
Starter/Gen. ....	9766H	7355	
Transaxle .....	2295R		6982
<b>T62241R2; T62241R3</b>			
Starter/Gen. ....	9766H	7355	
Trans. ....	2692R		6983
Transaxle .....	2295R		6982
<b>T62241R5</b>			
Trans. ....	2692R		6983
<b>T62241RO</b>			
Starter/Gen. ....	9766H	7355	
Trans. ....	2692R		6983
Transaxle .....	2295R		6982



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>T63231R</b>			
Trans. ....	2692R		6983
<b>T63341R1; T63341R3; T63361RO</b>			
Trans. ....	5125R		6868
<b>T81131RO</b>			
Transaxle ....	6474H	3810	6981
<b>T82231RO; T82241RO; T82251RO</b>			
Trans. ....	8833H		6973
<b>TCT340AR</b>			
Blade ....	125907X		6713BR
<b>TF1036AR; TF1238AR; TF1444AR</b>			
Deck ....	106085X		6672BR
Drive ....	125907X		6713BR
<b>TO2211RO; TO2231RO; TO2251RO</b>			
Trans. ....	8833H		6973
<b>TPTGK180CE</b>			
Blade ....	3703J		68100
Drive ....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>TS2051A</b>			
Blade ....	3703J		68100
P.T.O. ....	110884X		6714BR
<b>TYPGTB160AE</b>			
Drive ....	123796X		6432BR
<b>UC1238AR</b>			
Drive ....	125907X		6713BR
<b>UM1236A</b>			
Drive ....	124525X		6889
<b>UNGT1844AE</b>			
Drive ....	123554X		6894
<b>UNLT1038AE; UNLT1138AE</b>			
Drive ....	125907X		6713BR
<b>UNLT1238AE</b>			
Blade ....	125907X		6713BR
<b>V1JH44B</b>			
Blade ....	123451X		6881
<b>V10L36A; V10L36B</b>			
Drive ....	124525X		6889
<b>V16H44C</b>			
Blade ....	123461X		6881
<b>V1036B</b>			
Drive ....	124525X		6889
<b>V1238E</b>			
Blade ....	125907X		6713BR
P.T.O. ....	106085		6879
<b>V12538B</b>			
Blade ....	125907X		6713BR
<b>VKGTK180AG</b>			
P.T.O. ....	110884X		6714BR
<b>VKLR100AG</b>			
Drive ....	124525X		6889
<b>VL16H44B</b>			
Blade ....	123451X		6881
<b>VL16H44C; VL16H44D</b>			
Blade ....	123461X		6881
<b>VL125H38B; VL125H38C</b>			
Blade ....	126576X		6882
<b>VL1036A; VL1036B</b>			
Drive ....	124525X		6889
P.T.O. ....	124293X		6880
<b>VL1236C</b>			
Drive ....	126520X		6459BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>VL1296A; VL1438B</b>			
Blade ....	125907X		6713BR
<b>VL12536A</b>			
Drive ....	124525X		6889
<b>VL12538A</b>			
Blade ....	125907X		6713BR
<b>VL34036A; VLB12536A</b>			
Drive ....	124525X		6889
<b>VT1138AE; VT1238AE</b>			
Blade ....	125907X		6713BR
<b>VTGK180CE</b>			
Blade ....	3703J		68100
Drive ....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>VTLR080AE</b>			
Drive ....	124525X		6889
P.T.O. ....	124293X		6880
<b>VTLT120DE; VTLT140AE</b>			
Blade ....	125907X		6713BR
<b>WC12H38AE; WC16H38AE</b>			
Blade ....	123461X		6881
<b>WC1844AE</b>			
Blade ....	106381X		6892
Drive ....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>WD18H44A</b>			
Blade ....	123461X		6881
<b>WE10L36A; WE12R38A; WE125R38A</b>			
Drive ....	124525X		6889
<b>WE1136A</b>			
Deck ....	124293X		6880
Ground Drive ....	126520X		6459BR
<b>WET12R38A</b>			
Drive ....	124525X		6889
<b>WO2050A</b>			
Blade ....	3703J		68100
Drive ....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>WP12R38A</b>			
Drive ....	124525X		6889
<b>WP14H38A</b>			
Blade ....	123461X		6881
<b>WP1036A</b>			
Drive ....	124525X		6889
<b>WS1236A</b>			
Deck ....	124293X		6880
Ground Drive ....	126520X		6459BR
<b>WS12538A; X12D38A</b>			
Deck ....	106085X		6672BR
Ground Drive ....	125907X		6713BR
<b>X12D38AL; X14V38B</b>			
Blade ....	125907X		6713BR
<b>X18V44A</b>			
Blade ....	123796X		6432BR
<b>X18V44B; X18V44C</b>			
Deck ....	106085X		6672BR
Ground Drive ....	123796X		6432BR
<b>X125R38A</b>			
Drive ....	124525X		6889
<b>X1036A</b>			
Deck ....	124293X		6880
Ground Drive ....	124525X		6889
<b>X1036B; X1036C</b>			
Drive ....	124525X		6889

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>X1236A</b>			
Deck .....	124293X		6880
Traction; W/88 3/4" Belt O.C. ....	126520X		6459BR
Traction; W/89" Belt O.C. ....	124525X		6889
<b>X1844A</b>			
Blade .....	123796X	6432BR	
<b>XB12R38A; XB125R38MA</b>			
Drive .....	124525X		6889
<b>XC1120B</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>XC1122B</b>			
Blade .....	125907X	6713BR	
<b>XC1182B</b>			
Drive .....	123796X	6432BR	
<b>XEG1182HAR</b>			
Blade .....	3703J		68100
Drive .....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>XEG1182VAR</b>			
Drive .....	123796X	6432BR	
<b>XEL1120AR; XEL1122AR; XEY1142AR</b>			
Blade .....	125907X	6713BR	
<b>Y10L36A; Y10L36B; Y12R38A</b>			
Drive .....	124525X		6889
<b>Y18H44A; Y18H44B</b>			
Deck .....	106085X		6672BR
Drive .....	123461X		6881
<b>Y125H38A</b>			
Blade .....	126576X		6882
<b>Y1136C; Y1236C</b>			
Drive .....			6889
P.T.O. ....	124293X		6880
<b>Y1238E; Y1438B</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>Y1844A; Y1844B; Y1844C</b>			
Deck .....	106085X		6672BR
Drive .....	123796X		6432BR
<b>Y1850DD; Y2050A; Y2050B</b>			
Blade .....	3703J		68100
Drive .....	110883X		6899
P.T.O. ....	110884X		6714BR
<b>YC1238A; YC12538A</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>YE10L36B; YE10L36C; YE12R38A</b>			
Drive .....	124525X		6889
<b>YE1036A; YE1236C</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>YE1236D</b>			
Drive .....	124525X		6889
<b>YE1236E</b>			
Drive .....	126520X		6459BR
<b>YE1238A</b>			
Blade .....	125907X		6713BR
<b>YE1238E; YE1438B</b>			
Blade .....	125907X		6713BR
P.T.O. ....	106085		6879
<b>YE1442B</b>			
Blade .....	123461X		6881
<b>YE1850E; YE1850F</b>			
Blade .....	3703J		68100
Drive .....	110883X		6899

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>YE1850E; YE1850F - Continued</b>			
P.T.O. ....	110884X		6714BR
<b>YF1236A</b>			
Drive .....	124525X		6889
<b>YPGTV160AR</b>			
Drive .....	123796X		6432BR
<b>YPLR110BE; YPLR110BR; YPLR120BE</b>			
Drive .....	124525X		6889
P.T.O. ....	124293X		6880
<b>YPLT120DE</b>			
Drive .....	125907X		6713BR
<b>YPLT120DR; YPLT140AE</b>			
Blade .....	125907X		6713BR
<b>YPLTH140AE</b>			
Blade .....	123461X		6881
<b>YPLTH160ARE</b>			
Blade .....	120418X		6880
<b>YPLTV140AR</b>			
Blade .....	125907X		6713BR
<b>YPTGK180CR</b>			
Drive .....	123796X		6432BR
<b>YPPYTH140CR</b>			
Blade .....	123461X		6881
<b>YR1238B</b>			
Blade .....	125907X		6713BR
<b>YT12</b>			
Deck .....	106085X		6672BR
Trans. ....	108103X		6881
<b>YT14</b>			
Deck .....	106085X		6672BR
Spindle .....	11483		6943
<b>YT16</b>			
Blade .....	106085X		6672BR
Deck .....	106085X		6672BR
Trans. ....	108103X		6881
<b>YTH160</b>			
Deck .....	106085X		6672BR
Trans. ....	108103X		6881
<b>ROTO-HOE</b>			
<b>300CD</b>			
Belt; W/29" Belt O.C. ....			6829
Belt; W/35" Belt O.C. ....		2350	6835
Belt; W/38" Belt O.C. ....	361	2380	6838
Belt; W/46" Belt O.C. ....	3T44B		6846
Belt; W/64" Belt O.C. ....		2640	6864
Belt; W/65" Belt O.C. ....		2650	6865
Cultivator; W/38" Belt O.C. ....	3T44A		6838
<b>500; 550</b>			
Belt; W/51" Belt O.C. ....	101	2510	6851
Belt; W/59" Belt O.C. ....		2590	6859
<b>559H</b>			
Drive .....	108	2610	6861
<b>700EC</b>			
Eng. To J.S. ....	8422	3470	6947
J.S. To P.T.O. ....	8438		3V355
J.S. To Transaxle .....	8356	2346	
<b>800</b>			
Belt; W/1/2" Belt T.W. ....		2600	6860
Belt; W/21/32" Belt T.W. ....			6960
P.T.O.; W/3" Chipper .....	9090		B59
<b>800H</b>			
Belt; W/58" Belt O.C. ....	101A		6858
Belt; W/60" Belt O.C. ....	804		6860
<b>809H</b>			
Drive .....	108	2610	6861



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROTO-HOE - Continued</b>			
<b>2100</b>			
Blade; W/28" Belt O.C. ....	67	2280	6828
Blade; W/40" Belt O.C. ....	66	2400	6840
Blade; W/43" Belt O.C. ....	68	2430	6843
<b>2600</b>			
Blade; W/32" Belt O.C. ....		2320	6832
Blade; W/34" Belt O.C. ....		2340	6834
<b>Turf Star I</b>			
Eng. To Blade .....	7178	2630	6863
Eng. To Pulley; W/7" Pulley .....	7185	2520	6852
Speed Selector To J.S.; W/33" Belt O.C. ....	7193	3330	6933
Speed Selector To J.S.; W/40" Belt O.C. ....	7190		3V400
<b>Turf Star II</b>			
Eng. To Blade .....	7385	2660	6866
Eng. To Pulley; W/7" Pulley .....	8386	2560	6856
J.S. To J.S. ....	8387		3V450
Speed Selector To J.S. ....	7193	3330	6933
<b>ROYAL MOWER &amp; EDGER</b>			
<b>R-1</b>			
Belt .....		2300	6830
<b>RUGG</b>			
<b>5010R; 5011R</b>			
Belt .....	R240		6829
<b>5020L; 5020L1; 5020L2; 5021L</b>			
Blade .....	20843B		6825
Drive .....	20843A		6829
<b>5027G-1; 5029I; 5029R; 5030R; 5031E</b>			
Blade .....	R310		6825
Neutral Axis .....	R240		6829
<b>5031LE</b>			
Blade .....	20843B		6825
Drive .....	20843A		6829
<b>5031R; 5037G-1</b>			
Blade .....	R310		6825
Neutral Axis .....	R240		6829
<b>5040E; 5040R</b>			
Blade; W/26" Blade .....	20843U		6855
Drive; W/26" Deck .....	20843L		6835
<b>5049E2; 5049E4; 5049G2; 5049LE; 5049R2; 5049R4</b>			
Blade .....	20843M		6851
Drive .....	20843L		6835
<b>5050N</b>			
Blade .....	20843B		6825
Drive .....	20843A		6829
<b>5050R; 5050TE</b>			
Blade .....	R310		6825
Neutral Axis .....	R240		6829
<b>5051R; 5051R2</b>			
Blade .....	20843B		6825
Drive .....	20843A		6829
<b>5059R</b>			
Blade; W/25" Blade .....	20843M		6851
Drive; W/25" Deck .....	20843A		6829
<b>5060E; 5060G</b>			
Blade .....	R310		6825
Neutral Axis .....	R240		6829
<b>5060N</b>			
Blade .....	20843B		6825
Drive .....	20843A		6829
<b>5060R</b>			
Blade .....	R310		6825
Neutral Axis .....	R240		6829

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>RUGG - Continued</b>			
<b>5061N</b>			
Blade .....	20843B		6825
Drive .....	20843A		6829
<b>5061R; 5067G</b>			
Blade .....	R310		6825
Neutral Axis .....	R240		6829
<b>5068G; 5068N; 5068R; 5068S</b>			
Blade; W/39" Belt O.C. ....	20843N		6839
Blade; W/61" Belt O.C. ....	20843R		6861
Mower Drive .....	20843A		6829
<b>5069A; 5069AE; 5069E; 5069GE</b>			
Blade; W/32" Blade .....	20843T		6863
<b>5069H; 5069I</b>			
Blade .....	R310		6825
Neutral Axis .....	R240		6829
<b>5069R; 5069WE</b>			
Blade; W/32" Blade .....	20843T		6863
<b>5070E</b>			
Blade; W/26" Blade .....	20843U		6855
Drive; W/26" Deck .....	20843L		6835
<b>5071E</b>			
Blade; W/25" Belt O.C. ....	20843B		6825
Blade; W/29" Belt O.C. ....	20843A		6829
Mower Drive .....	20843L		6835
<b>5075G</b>			
Blade .....	R310		6825
Neutral Axis .....	R240		6829
<b>5080E; 5080R</b>			
Blade; W/26" Blade .....	20843T		6863
Drive; W/26" Deck .....	20843V		6850
<b>5081E; 5081E2; 5081R</b>			
Blade; W/59" Belt O.C. ....	20843W		6859
Blade; W/63" Belt O.C. ....	20843T		6863
Mower Drive .....	20843V		6850
<b>5081TXE</b>			
Blade; W/59" Belt O.C. ....	20843W		6859
Blade; W/63" Belt O.C. ....	20843T		6863
Mower Drive .....	20843X		6870
<b>5088E; 5088G; 5088G1; 5088L; 5088N; 5088R; 5088S; 5088SE; 5088T; 5088T1</b>			
Blade; W/39" Belt O.C. ....	20843N		6839
Blade; W/61" Belt O.C. ....	20843R		6861
Mower Drive .....	20843P		6849
<b>5088T2</b>			
Blade; W/39" Belt O.C. ....	20843N		6839
Blade; W/61" Belt O.C. ....	20843R		6861
Mower Drive .....	20843P		6849
<b>5089E</b>			
Blade; W/32" Blade .....	20843R		6861
<b>5098</b>			
Blade; W/32" Blade .....	20843T		6863
<b>5722LR; 5722R; 5722TR</b>			
Blade .....	20843B		6825
Drive .....	20843A		6829
<b>6000E; 6010E</b>			
Blade .....	20843Y		6873
Mower Drive .....	20843X		6870
Spindle .....	20843G		6836
<b>6011E</b>			
Blade; W/36" Belt O.C. ....	20843G		6836
Blade; W/73" Belt O.C. ....	20843Y		6873
Mower Drive .....	20843Z		6863
<b>6752R</b>			
Blade .....	31050G		6836
Drive .....	20843V		6850



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>RUGG - Continued</b>			
6762E; 6762R; 6762SE; 6762SE2; 6762SR2; 6762TE Mower Drive .....	20843V		6850
6782E Mower Drive .....	20843X		6870
7742LR; 7742R; 7742R2 Mower Drive .....	20843L		6835
7772E; 7772E2; 7772SE2; 7772TE Blade .....	20843J		6860
Mower Drive .....	20843L		6835
<b>SCAG POWER EQUIPMENT, INC.</b>			
<b>Gear Drive Rider</b>			
Deck Drive; W/61" Deck .....	48083		6645BR
Eng. To Deck; W/61" Deck .....	48207		6702BR
Transaxle; W/61" Deck .....	48085		6562BR
<b>Hydro Drive Rider</b>			
Blade - Right; W/48" SML Series Deck ..	48087		6864BR
Blade - Right; W/52" SM Series Deck ....	48285		7040BR
Blade - Right; W/52" SML Series Deck ..	48285		7040BR
Deck Drive; W/40" SML Series Deck .....	48086		6858BR
Deck Drive; W/48" SM Series Deck .....	48089		6701BR
Deck Drive; W/52" SM Series Deck .....	48286		6703BR
Deck Drive; W/61" SM Series Deck .....	48083		6645BR
Deck Drive; W/72" SM Series Deck .....	48359		6994
Eng. To Deck; W/61" Deck .....	48207		6702BR
Hydro.; W/40", 42", 48", 52" SML Series Deck .....			6835
<b>Magnum III</b>			
Blade - Left .....	48089		6701BR
W.P. ....		7385	
<b>SCR42-25CH</b>			
Pump .....	481978		6503BR
<b>SCR48-25CH; SCR48-27KA</b>			
Eng. To Deck .....	481979		6416BR
Pump .....	481978		6503BR
<b>SCR52-25CH; SCR52-27KA</b>			
Pump .....	481978		6503BR
<b>SCZ48V-22FX; SCZ48V-23CV-EFI; SCZ48V-28BS</b>			
Blade Drive .....	483239		6909BR
Eng. To Deck .....	483241		6688BR
Pump Drive .....	484372		6798BR
<b>SCZ52V-23FX; SCZ52V-25CV-EFI</b>			
Blade Drive .....	483240		6910BR
Eng. To Deck .....	483242		6905BR
Pump Drive .....	484372		6798BR
<b>SCZ61RD-31FX; SCZ61V-27FX; SCZ61V-29CV-EFI; SCZ61V-31FX; SCZ61V-31KA; SCZ61V-32BV; SCZ61V-34KH; SCZ61V-35CV-EFI; SCZ61V-36BV; SCZ61V-850FX</b>			
Blade Drive .....	483157		6911BR
Eng. To Deck .....	483741		6786BR
Pump Drive .....	483165		6739BR
<b>SCZ61V-921FX</b>			
Blade Drive .....	483157		6911BR
Eng. To Deck .....	483741		6786BR
Pump Drive .....	483165		6739BR
<b>SCZ72V-31FX</b>			
Eng. To Deck .....	484088		6746BR
Pump Drive .....	483165		6739BR
<b>SCZ72V-34KA; SCZ72V-34KH; SCZ72V-35CV-EFI; SCZ72V-36BV; SCZ72V-921FX</b>			
Blade Drive .....	484159		6913BR
Eng. To Deck .....	484088		6746BR
Pump Drive .....	483165		6739BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>			
<b>SFZ48-19KA; SFZ48-20FS; SFZ48-22KT; SFZ48-26BS; SFZ48-600FS</b>			
Deck Drive .....	483325		6906BR
Trans. ....	483314		6908BR
<b>SFZ52-19KA; SFZ52-20FS; SFZ52-24KT; SFZ52-26BS; SFZ52-600FS</b>			
Deck Drive .....	483326		6692BR
Trans. ....	483314		6908BR
<b>SFZ61-28BS; SFZ61-30BS; SFZ61-730FS</b>			
Deck Drive .....	484031		6733BR
Hydro. ....	483314		6908BR
<b>SFZP52-23FS; SFZP52-25BS</b>			
Deck Drive .....	483326		6692BR
Trans. ....	483314		6908BR
<b>SFZP61-24FS; SFZP61-27BS</b>			
Deck Drive .....	484031		6733BR
Trans. ....	484372		6798BR
<b>SPZ52-22FX</b>			
Deck Drive .....	483326		6692BR
Trans. ....	483314		6908BR
<b>SPZ61-23FX</b>			
Deck Drive .....	484031		6733BR
Trans. ....	484372		6798BR
<b>SR48</b>			
Eng. To Deck .....	A48081		6980
<b>SSZ-16BU</b>			
Blade - Right .....	48087		6864BR
Hydro. Pump .....			6861
<b>SSZ-16BV</b>			
Pump .....	48760		6793BR
<b>SSZ-18BV</b>			
Blade - Right .....	48087		6864BR
Hydro. Pump .....	48760		6793BR
<b>SSZ-18KH</b>			
Pump .....	48760		6793BR
<b>SSZ-42</b>			
Pump .....	48760		6793BR
<b>SSZ-48; SSZ48-18KH</b>			
Blade - Right .....	48087		6864BR
Eng. To Deck .....	48799		6665BR
Pump .....	48760		6793BR
<b>SSZ52-20CV; SSZ52-22CV</b>			
Blade - Right .....	481001		6568BR
Eng. To Deck .....	48285		7040BR
Pump .....	48760		6793BR
<b>SSZ61-20CV; SSZ61-22CV</b>			
Blade - Right .....	48996		6785BR
Pump .....	48760		6793BR
<b>SSZO18H W/SMZ-48</b>			
Blade - Right .....	48087		6864BR
Hydro. Pump .....			6861
<b>ST-12B; ST-13K; ST-13KA</b>			
Eng. To Deck; W/40" Deck .....	48086		6858BR
Eng. To Deck; W/48" Deck .....	48088		6904BR
Trans. ....	48085		6562BR
<b>ST-17KA</b>			
Trans. ....	48085		6562BR
<b>ST-18B</b>			
Eng. To Deck; W/48" Deck .....	48081		6815BR
Eng. To Deck; W/61" Deck .....	48083		6645BR
Trans. ....	48080		6839
<b>ST-18KH</b>			
Trans. ....	48085		6562BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>			
<b>STC40-17KA</b>			
Blade - Right .....	482091		6683BR
Trans. ....	482009		6552BR
<b>STC48-19KA; STC48-20CV</b>			
Deck .....	482138		6563BR
<b>STC48A-19KA; STC48A-20CV; STC48A-21KA</b>			
Deck Drive; Ser. No. 5810000 Thru 6669999 .....	482138		6563BR
Deck Drive; Ser. No. 7630000 Thru 9339999 .....	482529		6692BR
Deck Drive; Ser. No. A4800001 Thru A5599999 .....	482529		6692BR
Eng. To Deck; Ser. No. 5810000 Thru 6669999 .....	482137		6688BR
Trans.; Ser. No. 5810000 Thru 6669999 .....	482009		6552BR
Trans.; Ser. No. 7630000 Thru 8779999 .....	482531		6736BR
Trans.; Ser. No. 9250001 Thru 9339999 .....	482716		6736BR
Trans.; Ser. No. A4800001 Thru A5599999 .....	483084		6911BR
<b>STC48V-19KAI; STC48V-22FS; STC48V-23CV; STC48V-25CV; STC48V-26BS; STC48V-27BS; STC48V-651FS</b>			
Blade Drive .....	483239		6909BR
Eng. To Deck .....	483241		6688BR
Trans. ....	483172		7081BR
<b>STC52A-21KA; STC52A-23KA; STC52A-23LV; STC52A-24HN</b>			
Deck Drive; Ser. No. 5810000 Thru 6669999 .....	482140		6564BR
Deck Drive; Ser. No. 7630000 Thru 9339999 .....	482530		6719BR
Deck Drive; Ser. No. A4800001 Thru A5599999 .....	482530		6719BR
Eng. To Deck; Ser. No. 5810000 Thru 6669999 .....	482281		6574BR
Trans.; Ser. No. 5810000 Thru 6669999 .....	482009		6552BR
Trans.; Ser. No. 7630000 Thru 8779999 .....	482531		6736BR
Trans.; Ser. No. 9250001 Thru 9339999 .....	482716		6736BR
Trans.; Ser. No. A4800001 Thru A5599999 .....	483084		6911BR
<b>STC52V-22FX; STC52V-24FX; STC52V-25CV; STC52V-25CV-EFI; STC52V-27CV; STC52V-691FX</b>			
Blade Drive .....	483240		6910BR
Eng. To Deck .....	483242		6905BR
Trans. ....	483172		7081BR
<b>STC61V-23FX; STC61V-25CV; STC61V-26CV-EFI; STC61V-27BS; STC61V-27CV; STC61V-730FX</b>			
Blade Drive .....	483157		6911BR
Eng. To Deck .....	483243		6785BR
Trans. ....	483172		7081BR
<b>STCII-48V-22FS; STCII-48V-23CV</b>			
Blade Drive .....	483239		6909BR
<b>STCII-52V-22FX; STCII-52V-25CV-EFI</b>			
Blade Drive .....	483240		6910BR
<b>STCII-61V-23FX; STCII-61V-26CV-EFI</b>			
Blade Drive .....	483157		6911BR
Eng. To Deck .....	485636		6779BR
<b>STG-18KH</b>			
Trans. ....	48085		6562BR
<b>STG61-18KH</b>			
Blade - Right .....	48607		6845BR
Eng. To Deck .....	48083		6645BR
Pump .....	48085		6562BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>			
<b>STHM-18KH; STHM-20KH</b>			
Pump .....	48344		6835
<b>STHM61A-23CV</b>			
Pump .....	48912		6688BR
<b>STHM61V-23CV</b>			
Eng. To Deck .....	48912		6688BR
<b>STHM72A-23CV</b>			
Blade Drive .....	48295		B68
Eng. To Deck .....	481001		6568BR
<b>STT-27KA; STT-29KA-DFI</b>			
Pump .....	482873		6737BR
<b>STT-31BSD; STT-31BSG</b>			
Eng. To Deck .....	481460		6548BR
Pump .....	481461		6581BR
<b>STT-31BV</b>			
Pump .....	482873		6737BR
<b>STT52-22CH; STT52-22KA</b>			
Deck Drive .....	481557		6589BR
Eng. To Deck .....	481460		6548BR
Pump .....	481461		6581BR
<b>STT52-23CH</b>			
Deck .....	481557		6589BR
<b>STT52-25CH</b>			
Deck Drive .....	481557		6589BR
Eng. To Deck .....	481460		6548BR
Pump .....	481461		6581BR
<b>STT52A-22KA; STT52A-23CH</b>			
Deck Drive .....	482281		6574BR
Eng. To Deck .....	481460		6548BR
Pump .....	482171		6735BR
<b>STT52A-23KA</b>			
Deck Drive .....	482281		6574BR
Eng. To Deck; Ser. No. 9350000 & Before .....	481460		6548BR
Eng. To Deck; Ser. No. 9350001 Thru 9649999 .....	482876		6738BR
Pump; Ser. No. 6670001 Thru 7219999 .....	482171		6735BR
Pump; Ser. No. 7700001 Thru 7789999 .....	481749		6734BR
Pump; Ser. No. 8480001 Thru 8739999 .....	482641		6737BR
Pump; Ser. No. 9350001 Thru 9649999 .....	482873		6737BR
<b>STT52A-25CH</b>			
Deck Drive .....	482281		6574BR
Eng. To Deck .....	481460		6548BR
Pump; Ser. No. 6670001 Thru 7219999 .....	482171		6735BR
Pump; Ser. No. 7700001 Thru 7789999 .....	481749		6734BR
Pump; Ser. No. 8480001 Thru 8739999 .....	482641		6737BR
<b>STT52A-27CH</b>			
Deck Drive .....	482281		6574BR
Eng. To Deck; Ser. No. 8480001 Thru 8739999 .....	481460		6548BR
Eng. To Deck; Ser. No. 9350001 Thru 9649999 .....	482876		6738BR
Eng. To Deck; Ser. No. A5900001 Thru A9699999 .....	482876		6738BR
Pump; Ser. No. 8480001 Thru 8739999 .....	482641		6737BR
Pump; Ser. No. 9350001 Thru 9649999 .....	482873		6737BR
Pump; Ser. No. A5900001 Thru A9699999 .....	483085		6739BR
<b>STT52B-22CH; STT52B-22KA; STT52B-25CH</b>			
Deck Drive .....	481557		6589BR
Eng. To Deck .....	481460		6548BR
Pump .....	481461		6581BR
<b>STT52V-25CH-LP</b>			
Deck Drive .....	482281		6574BR
Eng. To Deck .....	482876		6738BR
Pump .....	483165		6739BR
<b>STT52V-26CH-EFI</b>			
Deck Drive .....	482281		6574BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>			
<b>STT52V-26CH-EFI - Continued</b>			
P.T.O. ....	482876		6738BR
Pump Drive .....	483166		6740BR
<b>STT52V-27CH</b>			
Deck Drive .....	482281		6574BR
Eng. To Deck .....	482876		6738BR
Pump .....	483165		6739BR
<b>STT61-22CH; STT61-25CH</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	481460		6548BR
Pump .....	481461		6581BR
<b>STT61A-22KA; STT61A-23CH</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	481460		6548BR
Pump .....	482171		6735BR
<b>STT61A-23KA; STT61A-25CH</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	481460		6548BR
Pump; Ser. No. 6670001 Thru 7219999 .	482171		6735BR
Pump; Ser. No. 7700001 Thru 7789999 .	481749		6734BR
Pump; Ser. No. 8480001 Thru 8739999 .	482641		6737BR
<b>STT61A-27CH</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck; Ser. No. 8480001 Thru 8739999	481460		6548BR
Eng. To Deck; Ser. No. 9350001 Thru 9649999	482876		6738BR
Eng. To Deck; Ser. No. A5900001 Thru A9699999	482876		6738BR
Pump; Ser. No. 8480001 Thru 8739999 .	482641		6737BR
Pump; Ser. No. 9350001 Thru 9649999 .	482873		6737BR
Pump; Ser. No. A5900001 Thru A9699999	483085		6739BR
<b>STT61A-27KA</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck; Ser. No. 9350000 & Before	481460		6548BR
Eng. To Deck; Ser. No. 9350001 Thru 9649999	482876		6738BR
Eng. To Deck; Ser. No. A5900001 Thru A9699999	482876		6738BR
Pump; Ser. No. 6670001 Thru 7219999 .	482171		6735BR
Pump; Ser. No. 7700001 Thru 7789999 .	481749		6734BR
Pump; Ser. No. 8480001 Thru 8739999 .	482641		6737BR
Pump; Ser. No. 9350001 Thru 9649999 .	482873		6737BR
Pump; Ser. No. A5900001 Thru A9699999	483085		6739BR
<b>STT61A-29KA-DFI</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck; Ser. No. 8480001 Thru 8739999	481460		6548BR
Eng. To Deck; Ser. No. 9350001 Thru 9649999	482876		6738BR
Pump; Ser. No. 8480001 Thru 8739999 .	482641		6737BR
Pump; Ser. No. 9350001 Thru 9649999 .	482873		6737BR
<b>STT61A-29KA-DFI-SS</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
Pump .....	483086		6740BR
<b>STT61A-31BSD; STT61A-31BSG</b>			
Blade - Right .....	481558		6566BR
Eng. To Deck .....	481460		6548BR
Pump .....	481461		6581BR
<b>STT61A-31BV</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
Pump .....	482873		6737BR
<b>STT61A-31BV-SS</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
Pump .....	483086		6740BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>			
<b>STT61B-22CH; STT61B-22KA; STT61B-25CH</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	481460		6548BR
Pump .....	481461		6581BR
<b>STT61V-25CH-LP</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
Pump .....	483165		6739BR
<b>STT61V-25KA</b>			
Deck Drive .....	481558		6566BR
P.T.O. ....	482876		6738BR
Pump Drive .....	483165		6739BR
<b>STT61V-25KBD</b>			
Deck Drive .....	481558		6566BR
P.T.O. ....	481460		6548BR
Pump Drive .....	483165		6739BR
<b>STT61V-25KBD-SS</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	481460		6548BR
Pump .....	483166		6740BR
<b>STT61V-26CH-EFI; STT61V-26DFI</b>			
Deck Drive .....	481558		6566BR
P.T.O. ....	482876		6738BR
Pump Drive .....	483166		6740BR
<b>STT61V-27CH</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
Pump .....	483165		6739BR
<b>STT61V-27KA</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
Pump .....	483165		6739BR
<b>STT61V-28CAT-SS</b>			
Deck Drive .....	483741		6786BR
Eng. To Deck .....	481460		6548BR
<b>STT61V-29KA-DFI-SS</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
Pump .....	483166		6740BR
<b>STT61V-31EFI-SS</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
<b>STT61V-31KB-DF</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	481460		6548BR
Pump Drive .....	482876		6738BR
<b>STT61V-35BVAC</b>			
Deck Drive .....	481558		6566BR
P.T.O. ....	482876		6738BR
Pump Drive .....	483166		6740BR
<b>STT61V-35BVAC-SS</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
Pump .....	483166		6740BR
<b>STT61V-35BV-SS</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
Pump .....	483166		6740BR
<b>STT61V-750KA</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
Pump .....	483165		6739BR
<b>STT61V-791DFI</b>			
Deck Drive .....	481558		6566BR
Eng. To Deck .....	482876		6738BR
Pump .....	483166		6740BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>			
<b>STT72A-27KA</b>			
Deck Drive .....	481980		6741BR
Eng. To Deck .....	481460		6548BR
Pump; Ser. No. 6670001 Thru 7219999	482171		6735BR
Pump; Ser. No. 7700001 Thru 7789999	481749		6734BR
Pump; Ser. No. 8480001 Thru 8739999	482641		6737BR
<b>STT72A-29KA-DFI</b>			
Deck Drive .....	481980		6741BR
Eng. To Deck; Ser. No. 8480001 Thru 8739999	481460		6548BR
Eng. To Deck; Ser. No. 9350001 Thru 9649999	482876		6738BR
Pump; Ser. No. 8480001 Thru 8739999	482641		6737BR
Pump; Ser. No. 9350001 Thru 9649999	482873		6737BR
<b>STT72A-29KA-DFI-SS</b>			
Deck Drive .....	481980		6741BR
Eng. To Deck .....	482876		6738BR
Pump .....	483086		6740BR
<b>STT72A-31BSD; STT72A-31BSG</b>			
Blade - Right .....	481980		6741BR
Eng. To Deck .....	481460		6548BR
Pump .....	481461		6581BR
<b>STT72A-31BV-SS</b>			
Deck Drive .....	481980		6741BR
Eng. To Deck .....	482876		6738BR
Pump .....	483086		6740BR
<b>STT72A-35BVAC-SS; STT72A-791DFI</b>			
Deck Drive .....	481980		6741BR
Eng. To Deck .....	482876		6738BR
Pump .....	483166		6740BR
<b>STT72V-25KBD</b>			
Deck Drive .....	481980		6741BR
P.T.O. ....	481460		6548BR
Pump Drive .....	483165		6739BR
<b>STT72V-26CH-EFI; STT72V-26DFI</b>			
Deck Drive .....	481980		6741BR
P.T.O. ....	482876		6738BR
Pump Drive .....	483166		6740BR
<b>STT72V-28CAT-SS</b>			
Deck Drive .....	481980		6741BR
Eng. To Deck .....	481460		6548BR
<b>STT72V-35BVAC</b>			
Deck Drive .....	481980		6741BR
P.T.O. ....	482876		6738BR
Pump Drive .....	483166		6740BR
<b>STTII-52V-26CH-EFI</b>			
Deck Drive .....	482281		6574BR
P.T.O. ....	482876		6738BR
<b>STTII-61V-25KA; STTII-61V-26CH-EFI; STTII-61V-26DFI; STTII-61V-31DFI; STTII-61V-35BVAC</b>			
Deck Drive .....	481558		6566BR
P.T.O. ....	482876		6738BR
<b>STTII-72V-26CH-EFI; STTII-72V-26DFI; STTII-72V-31DFI; STTII72V-35BVAC</b>			
Deck Drive .....	481980		6741BR
P.T.O. ....	482876		6738BR
<b>STWC48V-25CV; STWC48V-26KA-LC</b>			
Blade Drive .....	483239		6909BR
Eng. To Deck .....	483241		6688BR
Trans. ....	483172		7081BR
<b>STWC52A-25KA</b>			
Deck Drive .....	482530		6719BR
Trans. ....	483084		6911BR
<b>STWC52V-25KA; STWC52V-26KA-LC</b>			
Blade Drive .....	483240		6910BR
Eng. To Deck .....	483242		6905BR
Trans. ....	483172		7081BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>			
<b>STWC61A-27CV</b>			
Eng. To Deck .....	482652		6720BR
Trans.; Ser. No. 9660001 Thru 9669999	482716		6736BR
Trans.; Ser. No. A5600001 & After	483084		6911BR
<b>STWC61V-26KA-LC; STWC61V-27CV</b>			
Blade Drive .....	483157		6911BR
Eng. To Deck .....	483243		6785BR
Trans. ....	483172		7081BR
<b>STZ-20KH</b>			
Pump .....	48472		6844
<b>STZ52-20KH</b>			
Blade - Right .....	48285		7040BR
Eng. To Deck .....	48296		6615BR
Hydro. Pump .....			6853
Pump .....	48472		6844
<b>STZ61-20KH</b>			
Eng. To Deck .....	48752		6574BR
Pump .....	48749		6871BR
<b>Super Z 52"</b>			
Blade .....	48285		7040BR
<b>SVR36A-15FS; SVR36A-19FX; SVR36A-20FX; SVR36A-600FX</b>			
Deck Drive .....	483969		6400BR
Pump Drive .....	483520		6907BR
<b>SVR48V-22FX; SVR48V-24FX; SVR48V-691FX</b>			
Deck Drive .....	483966		6981BR
Pump Drive .....	483520		6907BR
<b>SVR52V-23FX; SVR52V-25CV-EFI; SVR52V-26FX; SVR52V-730FX</b>			
Deck Drive .....	484100		6901BR
Pump Drive .....	483520		6907BR
<b>SVR61V-25FX; SVR61V-26CV-EFI; SVR61V-29FX; SVR61V-801FX</b>			
Deck Drive .....	484197		6567BR
Pump Drive .....	483520		6907BR
<b>SZC36A-16HN; SZC36A-17KA; SZC36A-19KA; SZC42A-19KA</b>			
Pump Drive .....	483164		7005BR
<b>SZL48-22KT</b>			
Deck Drive .....	485350		6646BR
<b>SCHWEISS</b>			
<b>50D</b>			
Deck .....	230006		B100
Drive .....	230016		B158
<b>60D</b>			
Deck .....	230003		B115
<b>1840</b>			
Deck .....	230001		6987
<b>1850</b>			
Deck .....	230006		B100
Drive .....	230016		B158
<b>2040</b>			
Deck .....	230001		6987
<b>2050; 2350</b>			
Deck .....	230006		B100
Drive .....	230016		B158
<b>2360</b>			
Deck .....	230003		B115
<b>2372</b>			
Deck .....	230035		B128
<b>2450</b>			
Deck .....	230006		B100
Drive .....	230016		B158

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCHWEISS - Continued</b>			
2460			
Deck .....	230003		B115
<b>SCOTTS</b>			
S1642			
Deck Drive .....	M124895		6848BR
Drive .....	GX10065		6896
S1742			
Deck .....	M124895		6848BR
Traction .....	GX10062		6821BR
S2046			
Deck .....	GX10176		6707BR
Traction; Ser. No. 020000 & Before .....	GX10065		6896
Traction; Ser. No. 020001 & After .....	GX10644		6776BR
S2048; S2348			
Drive .....	M136927		7053BR
Primary .....	M110312		6818BR
Secondary .....	M110313		6650BR
S2546			
Deck .....	GX10176		6707BR
Drive .....	GX10065		6896
S2554			
Drive .....	M136927		7053BR
Primary .....	M110312		6818BR
Secondary .....	M118685		6843BR
<b>SEARS ROEBUCK</b>			
131.8000; 131.8010; 131.8020; 131.8030; 131.8050; 131.8051; 131.8060			
Belt .....	53558	2350	6835
131.8070; 131.8080; 131.8090; 131.8091; 131.8092; 131.8100; 131.8110; 131.8120; 131.8121; 131.8130			
Blade .....	54622	2250	6825
Trans. ....	53558	2350	6835
131.8140; 131.8150; 131.8151; 131.8160; 131.8161; 131.8170; 131.8180; 131.8190			
Blade .....	54622	2250	6825
Trans. ....	53558	2350	6835
131.8200; 131.8210; 131.8220; 131.8221; 131.8240; 131.8250; 131.8260			
Blade .....	54185		6843
Trans. ....	53987	2290	6829
131.8270; 131.8280; 131.8281; 131.8282; 131.8283			
Blade .....	54185		6843
Trans. ....		2280	6828
131.8300; 131.8380; 131.8390			
Blade .....	54622	2250	6825
Trans. ....	53558	2350	6835
131.8430			
Eng. To Deck .....	65284	2346	
Trans. ....	59884		6841
131.8440			
Drive .....	57955		6870
131.8450			
Gen. ....	65107		6731
Trans. ....	57955		6870
131.8460; 131.8470			
Trans. ....	59849	2730	6873
131.8530; 131.8531; 131.8532			
Eng. To Deck .....	65284	2346	
Trans. ....	59884		6841
131.8540; 131.8541			
Drive .....	STD304700		6870
131.8550			
Gen. ....	65107		6731

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
131.8550 - Continued			
Trans. ....	57955		6870
131.8560; 131.8561; 131.8570			
Trans. ....	59849	2730	6873
131.8814			
Blade .....	76019	2550	6855
Trans. ....	76018		6841
131.8817			
Blade .....	76274		6859
Deck .....	76275		6875
Trans. ....	76018		6841
131.8818			
P.T.O. ....	83691		6734
Primary .....	84287		6840
Secondary .....	84352		BX78
131.9532			
Blade .....	53157		6831
131.81321			
Blade; W/25" Belt O.C. ....	54622	2250	6825
Blade; W/43" Belt O.C. ....	55936		6943
Trans. ....	53558	2350	6835
131.81323; 131.81340; 131.81341			
Blade .....	55936		6943
131.81361; 131.81362; 131.81363; 131.81364			
Blade .....	65016		6946
Eng. To Deck .....	55936		6943
131.81580; 131.81581			
Drive .....	21170	2290	6829
131.83900			
Blade .....	54622	2250	6825
Trans. ....	53558	2350	6835
131.84670			
Trans. ....	59849	2730	6873
131.88380; 131.88381			
Drive .....			6834
131.88390			
Drive .....			6832
131.88391; 131.88393; 131.91440			
Blade .....	53157		6831
131.94616			
Blade .....	58577		6863
131.96100; 131.96105; 131.96200; 131.96210; 131.96230; 131.96235			
Blade .....	54622	2250	
Transaxle .....	53558		6835
131.96251			
Blade .....	67438		6847
Trans. ....	67346		6839
131.96260			
Blade .....	59884		6841
131.96261; 131.96263			
Blade .....	67438		6847
Trans. ....	67346		6839
131.96270; 131.96280; 131.96280-1; 131.96281; 131.96285; 131.96286; 131.96300; 131.96310; 131.96312; 131.96315			
Blade .....	59884		6841
131.96316			
Blade .....	59884		6841
131.96317			
Blade .....	70637		6840
131.96321; 131.96323			
Blade .....	67403		6860



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
131.96326			
Trans. ....	67346		6839
131.96330			
Blade .....	67438		6847
Transaxle .....	67346		6839
131.96350; 131.96351; 131.96356			
Blade .....	59884		6841
131.96361; 131.96363			
Eng. To Deck .....	67788		6878
Trans. ....	67398		6853
131.96400; 131.96410; 131.96412; 131.96413; 131.96415; 131.96416; 131.96417; 131.96450; 131.96451; 131.96460			
Blade .....	58577		6863
Drive .....	58406	2650	6865
131.96461; 131.96465; 131.96467			
Blade .....	58577		6863
Drive .....	58406	2650	6865
131.96500; 131.96501; 131.96502; 131.96510; 131.96512			
Deck .....		2490	6849
131.96513			
Blade .....		2490	6849
131.96600; 131.96601; 131.96602; 131.96610			
Deck .....		2490	6849
131.96612			
Blade .....		2490	6849
131.96615; 131.96616			
Deck .....		2490	6849
131.96700			
Blade .....	65016		6946
Drive .....	STD304700		6870
131.96710; 131.96712			
Blade .....	65016		6946
Gen. ....	65133		6732
131.96800; 131.96810; 131.96820; 131.96830			
Blade .....	67438		6847
Transaxle .....	67346		6839
131.96831			
Transaxle .....	67346		6839
131.96840; 131.96850			
Blade .....	67398		6853
Trans. ....	67346		6839
131.96860; 131.96861			
Transaxle .....	67346		6839
131.96890; 131.96891; 131.96892			
Blade .....	70637		6840
131.96900; 131.96901; 131.96910			
Blade .....	67438		6847
Transaxle .....	67346		6839
131.96911			
Trans. ....	71240		A90
131.96917; 131.96920; 131.96921; 131.96927; 131.96930			
Blade .....	67438		6847
Transaxle .....	67346		6839
131.96940; 131.96941			
Blade .....	67398		6853
Trans. ....	67346		6839
131.96950			
Blade .....	71635		6863
Trans. ....	67346		6839
131.96950X			
Blade .....	71635		6863

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
131.96960; 131.96970; 131.96970X; 131.96971; 131.96972; 131.96990; 131.96990-1; 131.96991			
Trans. ....	71240		A90
131.97450; 131.97460; 131.97470			
Belt .....	53747	1300	6730
131.98830			
Eng. To Deck .....	65016		6946
Trans. ....	57955		6870
131.250810			
Blade .....	59884		6841
131.881801			
P.T.O. ....	83691		6734
Primary .....	84287		6840
Secondary .....	84352		BX78
131.962512; 131.962513; 131.962612; 131.962613; 131.962632; 131.962633			
Blade .....	67438		6847
Trans. ....	67346		6839
131.962860			
Blade .....	59884		6841
131.963170			
Blade .....	70637		6840
131.963212; 131.963213; 131.963232; 131.963233			
Blade .....	67403		6860
131.963262; 131.963263			
Blade .....	68620		6856
Trans. ....	67346		6839
131.965300			
Blade .....	74278	2880	6880
Deck .....	74277	2610	6861
Trans. ....	73794	2940	6894
131.969020			
Trans. ....	67346		6839
Transaxle .....	67346		6839
131.969120; 131.969170; 131.969220; 131.969221; 131.969310			
Transaxle .....	67346		6839
131.969460			
Blade .....	67398		6853
Eng. To Deck .....	74212		6857
Trans. ....	67346		6839
131.969730; 131.969800; 131.969802; 131.969930			
Trans. ....	73794		6894
131.9692201			
Transaxle .....	67346		6839
134.81580; 134.81581			
Drive .....	21170	2290	6829
247.27020			
Deck .....	7540754		6576BR
Drive .....	7540453		6617BR
247.203732			
Deck Drive .....	954-04060C		6776BR
Drive - Lower .....	954-0467A		6606BR
Drive - Upper .....	954-04208A		7051BR
502.8130			
Drive .....	304350	2350	6835
502.25120			
Belt; W/43" Belt O.C. ....	23072		6843
Belt; W/62" Belt O.C. ....	23098		6793BR
502.25121			
Eng. To Gear Box .....	23098		6793BR
Gear Box To Transaxle .....	23072		6843

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
502.25130			
Belt; W/43" Belt O.C. ....	23072		6843
Belt; W/62" Belt O.C. ....	23098		6793BR
502.25131			
Eng. To Gear Box .....	23098		6793BR
Gear Box To Transaxle .....	23072		6843
502.25516A			
Blade .....	37X12		6449BR
Trans. ....	37X65		6453BR
502.25601; 502.25602; 502.25603; 502.25604; 502.25605; 502.25606			
Blade .....	25667		6856
Trans. ....	20715		6837
502.25609			
Blade .....	25667		6856
Trans. ....	37X5		6837
502.25611; 502.25612; 502.25613			
Blade .....	25686		6822
Drive .....	37X5		6837
502.25800 (LT10)			
Deck .....	21649		6449BR
Transaxle .....	21615		6895
502.25800; 502.25801			
Cross Drive .....			6846
Deck .....	21649		6449BR
Trans. ....	21615		6895
502.25810 (LT10)			
Deck .....	21649		6449BR
Transaxle .....	21615		6895
502.25810			
Cross Drive .....			6846
Deck .....	21649		6449BR
Trans. ....	21615		6895
502.25830 (LT10)			
Deck .....	21649		6449BR
Transaxle .....	21615		6895
502.25830			
Blade .....	21649		6449BR
Cross Drive .....			6846
Trans.; W/37" Belt O.C. ....	20715		6837
Trans.; W/95" Belt O.C. ....	37X11		6452BR
502.25831			
Blade .....	37X3		6846
Deck .....	37X12		6449BR
Trans. ....	37X11		6452BR
502.25890 (LT10)			
Deck .....	21649		6449BR
Transaxle .....	21615		6895
502.25890			
Cross Drive .....			6846
Deck .....	21649		6449BR
Trans. ....	21615		6895
502.25891 (LT10)			
Deck .....	21649		6449BR
Transaxle .....	21615		6895
502.25891			
Cross Drive .....			6846
Deck .....	21649		6449BR
Trans. ....	21615		6895
502.25900; 502.25910			
Eng. ....	21058		6863
Eng. To Gear Box .....	23098		6793BR
Gear Box To Transaxle .....	23072		6843
502.25981			
Blade .....	37X43		6601BR
Drive .....	37X55		6891
502.52900; 502.52910			
Eng. To Gear Box .....	21058		6863

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
502.63029X1			
Blade .....	20556		6848
Deck .....	20555		6841
Trans. ....	20716		6837
502.81300; 502.81301			
Blade .....	20555		6841
Deck .....	20556		6848
Transaxle .....	20716		6837
502.81370; 502.81373; 502.81375			
Blade .....	20717		6856
Trans. ....	20716		6837
502.81377			
Blade .....	37X2		6848
502.81380; 502.81381			
Blade .....	20717		6856
Trans. ....	20716		6837
502.81390			
Cross Drive .....	21059		6844
Deck .....	21058		6863
Trans. ....	20716		6837
502.154190			
Blade .....	37X57		6498BR
Trans. ....	37X65		6453BR
502.230891			
Blade .....			6846
Deck .....	21649		6449BR
Trans. ....	21615		6895
502.245210			
Blade .....	37X59		6672BR
Trans. ....	37X27		6434BR
502.250291			
Blade .....	37X2		6848
502.250791			
Blade .....	20555		6841
Deck .....	20556		6848
Trans. ....	20716		6837
502.250840; 502.250841			
Cross Drive .....	23223		6895
Deck .....	23214		6859
Drive .....	21615		6895
502.250842			
Cross Drive .....	23223		6895
Deck .....	37X16		6859
Drive .....	21615		6895
502.250843			
Blade .....	37X22		6642BR
Deck; W/62" Belt O.C. ....	37X40		6451BR
Deck; W/86" Belt O.C. ....	37X62		6400BR
Trans. ....	37X11		6452BR
502.250849			
Blade .....	21649		6449BR
Cross Drive .....			6846
Drive .....	21615		6895
502.250890; 502.250891; 502.250892; 502.250893			
Cross Drive .....			6846
Deck .....	21649		6449BR
Drive .....	21615		6895
502.250894			
Cross Drive .....			6846
Deck .....	37X12		6449BR
Drive .....	21615		6895
502.251220; 502.251250			
Drive .....	37X65		6453BR
502.251341			
Blade .....	21649		6449BR
Cross Drive .....			6846



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>502.253760</b>			
Blade .....	37X40		6451BR
Cross Drive .....	37X22		6642BR
Drive .....	37X26		6463BR
<b>502.254110</b>			
Blade .....	37X12		6449BR
Trans. ....	37X65		6453BR
<b>502.254111; 502.254112; 502.254113;</b>			
<b>502.254114</b>			
Deck .....	37X12		6449BR
Motion Drive .....	37X65		6453BR
<b>502.254120</b>			
Deck .....	37X12		6449BR
Trans. ....	37X38		6425BR
<b>502.254121</b>			
Blade .....	37X12		6449BR
Drive .....	37X38		6425BR
<b>502.254130; 502.254131</b>			
Trans. ....	37X38		6425BR
<b>502.254132</b>			
Blade .....	37X57		6498BR
Drive .....	37X38		6425BR
<b>502.254140</b>			
Blade .....	37X57		6498BR
Trans. ....	37X51		6376
<b>502.254142</b>			
Blade .....	37X57		6498BR
Traction .....	37X51		6376
<b>502.254152</b>			
Blade .....	37X57		6498BR
Trans. ....	37X51		6376
<b>502.254153</b>			
Blade; W/54" Belt O.C. ....	37X57		6498BR
Blade; W/55" Belt O.C. ....	37X12		6449BR
Drive; W/37" Belt O.C. ....	37X51		6376
Drive; W/40" Belt O.C. ....	37X38		6425BR
<b>502.254160</b>			
Blade; W/30" Belt O.C. ....	37X65		6453BR
Blade; W/54" Belt O.C. ....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>502.254170; 502.254171</b>			
Blade .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>502.254172</b>			
Blade .....	37X57		6498BR
Drive .....	37X57		6498BR
<b>502.254180; 502.254190</b>			
Blade .....	37X57		6498BR
Trans. ....	37X65		6453BR
<b>502.254210; 502.254211</b>			
Blade .....	37X59		6672BR
Trans. ....	37X27		6434BR
<b>502.254260</b>			
Blade .....	37X40		6451BR
Cross Drive .....	37X54		5716
<b>502.254280</b>			
Trans. ....	37X55		6891
<b>502.254281; 502.254290</b>			
Blade .....	37X43		6601BR
Trans. ....	37X55		6891
<b>502.254380</b>			
Deck .....	37X63		6601BR
Drive .....	37X61		6452BR
<b>502.254580</b>			
Blade .....	106085X		6672BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>502.254690</b>			
Blade .....	37X43		6601BR
<b>502.254970</b>			
Trans. ....	37X61		6452BR
<b>502.254980</b>			
Deck .....	37X62		6400BR
Trans. ....	37X61		6452BR
<b>502.254981; 502.254982</b>			
Deck .....	37X62		6400BR
Drive .....	37X61		6452BR
<b>502.255010; 502.255011; 502.255020;</b>			
<b>502.255030; 502.255040; 502.255050;</b>			
<b>502.255060; 502.255071; 502.255090;</b>			
<b>502.255091</b>			
Drive .....	37X65		6453BR
<b>502.255092; 502.255093; 502.255094</b>			
Drive .....	37X65		6453BR
<b>502.255110; 502.255111; 502.255112;</b>			
<b>502.255120</b>			
Deck .....	37X63		6601BR
Drive .....	37X61		6452BR
<b>502.255140; 502.255141; 502.255142</b>			
Blade .....			6846
Deck .....	21649		6449BR
Trans. ....	21615		6895
<b>502.255143</b>			
Blade .....	37X3		6846
Deck .....	37X12		6449BR
Trans. ....	37X61		6452BR
<b>502.255150; 502.255151</b>			
Cross Drive .....	23749		6899
Deck .....	23748		6862
Drive .....	21615		6895
<b>502.255160; 502.255161</b>			
Cross Drive .....			6846
Deck .....	21649		6449BR
Drive .....	21615		6895
<b>502.255170; 502.255171; 502.255172</b>			
Motion Drive .....	37X65		6453BR
<b>502.255180</b>			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X62		6400BR
<b>502.255190; 502.255191</b>			
Cross Drive .....	23749		6899
Deck .....	23748		6862
Drive .....	21615		6895
<b>502.255192</b>			
Deck .....	37X62		6400BR
Trans. ....	37X61		6452BR
<b>502.255193</b>			
Motion Drive .....	37X61		6452BR
Mower Drive .....	37X62		6400BR
<b>502.255290; 502.255291; 502.255292</b>			
Cross Drive .....			6846
Deck .....	23882		A57
Drive .....	21615		6895
<b>502.255320</b>			
Blade .....	23749		6899
Deck .....	23748		6862
Trans. ....	21615		6895
<b>502.255321; 502.255322</b>			
Blade .....	37X22		6642BR
Deck .....	37X40		6451BR
Trans. ....	37X11		6452BR
<b>502.255380; 502.255381</b>			
Blade .....	37X43		6601BR
Trans. ....	37X45		6490BR

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>502.255530; 502.255531</b>			
Deck .....	37X63		6601BR
Drive .....	37X61		6452BR
<b>502.255610</b>			
Blade .....	37X7		6856
Trans. ....	37X51		6376
<b>502.255620; 502.255621; 502.255622;</b>			
<b>502.255623</b>			
Blade .....	37X12		6449BR
Trans. ....	37X38		6425BR
<b>502.255630; 502.255631</b>			
Blade .....	37X50		6854
Traction .....	37X38		6425BR
<b>502.255632; 502.255633</b>			
Blade .....	37X57		6498BR
Trans. ....	37X38		6425BR
<b>502.255634</b>			
Drive .....	37X38		6425BR
<b>502.255640; 502.255641; 502.255642</b>			
Belt .....	37X50		6854
Traction .....	37X51		6376
<b>502.255644</b>			
Blade .....	37X57		6498BR
Trans. ....	37X51		6376
<b>502.255650; 502.255651</b>			
Belt .....	37X50		6854
Traction .....	37X51		6376
<b>502.255652</b>			
Blade .....	37X57		6498BR
Trans. ....	37X51		6376
<b>502.255660</b>			
Trans. ....	37X51		6376
<b>502.255710</b>			
Blade .....	37X34		6877
Cross Drive .....	37X54		5716
Trans. ....	37X27		6434BR
<b>502.255711; 502.255712; 502.255713</b>			
Blade .....	37X34		6877
Trans. ....	37X27		6434BR
<b>502.255750</b>			
Blade .....	37X40		6451BR
Cross Drive .....	37X54		5716
Eng. To Trans. ....	37X55		6891
<b>502.255751; 502.255752; 502.255760;</b>			
<b>502.255761</b>			
Blade .....	37X40		6451BR
Cross Drive .....	37X54		5716
<b>502.255780; 502.255781</b>			
Blade .....	37X43		6601BR
Trans. ....	37X45		6490BR
<b>502.255790</b>			
Blade .....	37X43		6601BR
Drive .....	37X55		6891
<b>502.255791</b>			
Blade .....	37X43		6601BR
Transaxle .....	37X45		6490BR
<b>502.255822</b>			
Blade .....	106085X		6672BR
Trans. ....	105876X		6893
<b>502.256010</b>			
Blade .....	20717		6856
Trans. ....	20716		6837
<b>502.256011; 502.256012</b>			
Blade .....	37X7		6856
<b>502.256020</b>			
Blade .....	20717		6856

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>502.256020 - Continued</b>			
Traction .....	20716		6837
Trans. ....	20715		6837
<b>502.256021</b>			
Blade .....	37X7		6856
Trans. ....	37X5		6837
<b>502.256030</b>			
Blade .....	20717		6856
Traction .....	20716		6837
Trans. ....	20715		6837
<b>502.256031</b>			
Blade .....	37X7		6856
Trans. ....	37X5		6837
<b>502.256032</b>			
Blade .....	20717		6856
Trans. ....	20715		6837
<b>502.256033; 502.256034; 502.256036</b>			
Blade .....	37X7		6856
Trans. ....	37X5		6837
<b>502.256040</b>			
Blade .....	20717		6856
Traction .....	20716		6837
Trans. ....	20715		6837
<b>502.256041</b>			
Blade .....	20717		6856
Trans. ....	20715		6837
<b>502.256042</b>			
Blade .....	37X7		6856
Trans. ....	37X5		6837
<b>502.256050</b>			
Blade .....	20717		6856
Traction .....	20716		6837
Trans. ....	20715		6837
<b>502.256051</b>			
Blade .....	37X7		6856
Trans. ....	37X5		6837
<b>502.256060</b>			
Blade .....	20717		6856
Traction .....	20716		6837
Trans. ....	20715		6837
<b>502.256061; 502.256062</b>			
Blade .....	20717		6856
Trans. ....	20715		6837
<b>502.256063</b>			
Blade .....	37X7		6856
Trans. ....	37X5		6837
<b>502.256070</b>			
Traction .....	20716		6837
Trans. ....	20715		6837
<b>502.256071</b>			
Trans. ....	37X5		6837
<b>502.256080</b>			
Trans. ....	20715		6837
<b>502.256090</b>			
Blade .....	20717		6856
Trans. ....	20716		6837
<b>502.256091</b>			
Blade .....	37X7		6856
Trans. ....	37X6		6837
<b>502.256092; 502.256093; 502.256094;</b>			
<b>502.256095</b>			
Blade .....	37X7		6856
Trans. ....	37X5		6837
<b>502.256110; 502.256111; 502.256112</b>			
Blade .....	21649		6449BR
Trans. ....	20715		6837



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
502.256113; 502.256114; 502.256115; 502.256116; 502.256117; 502.256117A; 502.256118; 502.256119			
Blade .....	37X12		6449BR
Trans. ....	37X5		6837
502.256120; 502.256121			
Blade .....	21649		6449BR
Trans. ....	20715		6837
502.256122; 502.256123; 502.256124; 502.256125; 502.256126			
Blade .....	37X12		6449BR
Trans. ....	37X5		6837
502.256127; 502.256128			
Blade .....	37X12		6449BR
502.256130; 502.256131			
Blade .....	21649		6449BR
Trans. ....	20715		6837
502.256132; 502.256133; 502.256134; 502.256135; 502.256136; 502.256136A; 502.256137; 502.256138			
Blade .....	37X12		6449BR
Trans. ....	37X5		6837
502.256139			
Blade .....	37X12		6449BR
502.256140			
Blade .....	21649		6449BR
Trans. ....	20715		6837
502.256141; 502.256142; 502.256160; 502.256170; 502.256171			
Blade .....	37X12		6449BR
Trans. ....	37X5		6837
502.256172			
Blade .....	37X12		6449BR
Trans. ....	37X51		6376
502.256180; 502.256181; 502.256190			
Blade .....	37X12		6449BR
Trans. ....	37X5		6837
502.256210			
Drive .....	37X65		6453BR
502.257010			
Eng. ....	37X15		6862
Trans. ....	37X14		6843
502.257040; 502.257041; 502.257042			
Drive .....	37X23		6843
Trans. ....	37X15		6862
502.257043			
Trans. ....	37X26		6463BR
502.257310			
Blade .....	37X57		6498BR
Drive .....	37X65		6453BR
502.257330; 502.258170			
Motion Drive .....	37X65		6453BR
502.259120			
Blade .....	37X12		6449BR
Trans. ....	37X38		6425BR
502.259280			
Blade .....	37X43		6601BR
Trans. ....	37X55		6891
502.259281			
Blade .....	37X43		6601BR
Trans. ....	37X45		6490BR
502.354264			
Deck .....	37X40		6451BR
502.522653			
Blade .....	37X57		6498BR
Trans. ....	37X51		6376

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
502.813770			
Blade .....	20555		6841
Deck .....	20556		6848
Transaxle .....	20716		6837
502.813780			
Blade .....	20556		6848
Deck .....	20556		6848
Trans. ....	20716		6837
502.2256116			
Blade .....	37X12		6449BR
Trans. ....	37X5		6837
502.2508491			
Blade .....			6846
Deck .....	21649		6449BR
Trans. ....	21615		6895
502.2560811			
Trans. ....	37X5		6837
502.2561121; 502.2561122; 502.2561321			
Blade .....	37X12		6449BR
536.25094			
Deck .....	48044		6454BR
Drive .....	39454		6463BR
536.81330			
Blade; W/70" Belt O.C. ....	42111		6630BR
Blade; W/88" Belt O.C. ....	39454		6463BR
536.81340; 536.81341; 536.81342			
Drive .....	LP2154	2200	6820
536.81350; 536.81351; 536.81352; 536.81353; 536.81354; 536.81356			
Belt .....	LP708	3380	6938
536.81360; 536.81361; 536.81362			
Blade; W/70" Belt O.C. ....	42111		6630BR
Blade; W/88" Belt O.C. ....	39454		6463BR
536.81450; 536.81451; 536.81452; 536.81453; 536.81454			
Drive .....	RM2754	2280	6828
536.81456			
Drive .....	RM3333	2275	
536.85316; 536.85870			
Belt .....	RM2543		6828
536.96310			
Blade .....	45186	2630	
Trans. ....			6856
536.96320			
Blade .....	45186	2630	
Trans. ....	43979		6856
536.96330			
Blade .....	43066		6520BR
Speed Reducer; Long .....	43947		6855
Speed Reducer; Short .....	43946		6846
Transaxle .....	39454		6463BR
536.96331			
Blade .....	43066		6520BR
Transaxle .....	39454		6463BR
536.96360			
Blade .....	43066		6520BR
Speed Reducer; Long .....	43947		6855
Speed Reducer; Short .....	43946		6846
Transaxle .....	39454		6463BR
536.96361; 536.96362			
Blade .....	43066		6520BR
Transaxle .....	39454		6463BR
536.250820; 536.250821; 536.250822; 536.250823			
Blade .....	45186	2630	
Trans. ....	43979		6856

Lawn & Garden Equipment

RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
536.250850			
Blade .....	47201		6825
Drive .....	47200		6829
536.250860; 536.250870		2440	
Blade .....	45187		6856
Drive .....	43979		
536.250910; 536.250920; 536.250921; 536.250922			
Blade .....	43066		6520BR
Trans. ....	39455		6863
536.250930; 536.250931; 536.250933; 536.250940; 536.250941; 536.250942			
Blade .....	48044		6454BR
Trans. ....	39454		6463BR
536.250960			
Blade .....	43066		6520BR
Trans. ....	39454		6463BR
536.252570; 536.252571			
Deck .....	314108		6537BR
Drive .....	335708		6881
536.255110; 536.255112		2630	
Blade .....	45186		6856
Trans. ....	43979		
536.255113		2630	
Deck .....	45186		6863
Drive .....	43979		6856
536.255210; 536.255212			
Blade .....	48044		6454BR
Trans. ....	39454		6463BR
536.255220; 536.255221			
Blade .....	47390		6871
Trans. ....	43979		6856
536.255230; 536.255231			
Blade .....	43066		6520BR
Trans. ....	43979		6856
536.255232			
Deck .....	43066		6520BR
Drive .....	43979		6856
536.255240			
Blade .....	43066		6520BR
Trans. ....	43979		6856
536.255250			
Blade .....	47390		6871
Trans. ....	43979		6856
536.255280			
Deck .....	49878		6467BR
Primary Drive .....	50597		6830
Secondary Drive .....	49580	2405	
536.255860			
Deck .....	300680		6555BR
536.255861			
Deck .....	300680		6408BR
536.255870; 536.255880			
Deck .....	318372		6702BR
Drive .....	314120		6887
536.257670			
Deck .....	314108		6537BR
Drive .....	314120		6887
536.270111; 536.270112; 536.270211; 536.270212			
Deck .....	37X57		6498BR
Drive .....	37X65		6453BR
536.270270			
Blade .....	37X111		6657BR
536.270280; 536.270281			
Deck .....	37X111		6657BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
536.270280; 536.270281 - Continued			
Drive .....	37X129		6830
536.270290			
Deck .....	37X111		6657BR
Drive .....	37X110		6656BR
536.657000; 536.657020		2440	
Blade .....	45187		6856
Drive .....	43979		
536.657040			
Blade .....	47390		6871
Trans. ....	43979		6856
536.658080			
Blade .....	48044		6454BR
Trans. ....	39454		6463BR
536.963100		2630	
Blade .....	45186		6856
Trans. ....	43979		
536.963310; 536.963630; 536.963631			
Blade .....	43066		6520BR
Transaxle .....	39454		6463BR
536.963700			
Deck .....	46466		6983
Transaxle .....	39454		6463BR
536.990700			
Traction .....	49570		6837
538.81980; 538.81981; 538.81982; 538.81990; 538.81991		2200	
Belt .....			6820
564.250910			
Deck .....	43066		6520BR
Drive .....	39455		6863
809.85621; 809.85623; 809.85624; 809.85770; 809.85775; 809.85811; 809.85812; 809.85813; 809.85814; 809.85816			
Belt .....	2543		6828
917.2550			
Starter/Gen. ....	3754H1		3V315
Trans. ....		3790	6979
917.8310			
Belt; W/43" Belt O.C. ....	4384H		6943
917.8320; 917.8321; 917.8322			
Blade; W/43" Belt O.C. ....	55936		6943
Blade; W/71" Belt O.C. ....	55941		6971
917.8330; 917.8331; 917.8340; 917.8341			
Blade; W/31" Belt O.C. ....	65107		6731
Blade; W/43" Belt O.C. ....	55936		6943
Drive .....	STD304700		6870
917.8360; 917.8361; 917.8362; 917.8370; 917.8371; 917.8372		3480	
Blade; W/48" Belt O.C. ....			6948
Blade; W/49" Belt O.C. ....	5092H		6949
Transaxle .....	5091H		6982
917.8400; 917.8420			
Drive .....	STD304700		6870
Gen. ....	65107		6731
917.9950; 917.9951			
Gen. ....	3754H1		6733
Trans. ....	5091H		6982
917.25000		3810	
Trans. ....	6474H		6981
917.25010; 917.25011; 917.25020; 917.25021		7320	
Gen. ....	5436H		3810
Trans. ....	6474H		6981
917.25030; 917.25040; 917.25041		3810	
Trans. ....	6474H		6981



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.25050; 917.25051; 917.25060; 917.25061; 917.25070	8833H		6973
917.25080; 917.25081; 917.25090; 917.25091; 917.25092	5436H 6474H	7320 3810	6981
917.25100	6474H 3754H1		6981 3V315
917.25100 Suburban	6474H 3754H1		6981 3V315
917.25101; 917.25110	6474H 3754H1		6981 3V315
917.25110 Suburban	6474H 3754H1		6981 3V315
917.25111; 917.25120; 917.25121; 917.25130	6474H 3754H1		6981 3V315
917.25130 Suburban	6474H 3754H1		6981 3V315
917.25131	6474H 3754H1		6981 3V315
917.25140; 917.25141; 917.25150; 917.25151; 917.25160; 917.25161	8845R		6874
917.25170	6474H 3754H1		6981 3V315
917.25180; 917.25181; 917.25190; 917.25191	2692R		6983
917.25200; 917.25201	9766H 2295R	7355	6982
917.25220	6474H 3754H1 6474H		6981 3V315 6981
917.25221; 917.25230; 917.25231	5436H 6474H	7320 3810	6981
917.25260	3754H1 6474H		3V315 6981
917.25261	5436H 6474H	7320 3810	6981
917.25263	7080J 4798J 4866J		6861 6878 6878
917.25264	7080J 4798J 4866J		6861 6878 6878
917.25268	100670N 102726X		6879 6947
917.25290; 917.25302; 917.25310; 917.25311	3754H1 6474H		3V315 6981

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.25311 Super Tractor			6981
917.25340; 917.25350; 917.25352; 917.25370; 917.25371	3754H1 6474H		3V315 6981
917.25380; 917.25381	9766H 2295R	7355	6982
917.25400	3754H1		3V315 6979
917.25420; 917.25430	8833H 5436H	3730 7320	6973
917.25440	8833H		6973
917.25450; 917.25460; 917.25470	8833H 5436H	3730 7320	6973
917.25480	3754H1 6474H		3V315 6981
917.25481	6474H		6981
917.25490	8833H 5436H	3730 7320	6973
917.25500; 917.25501	3754H1 5436H 8100H		3V315 6979
917.25510; 917.25510A; 917.25510B; 917.25511; 917.25520; 917.25520A; 917.25520B; 917.25550	3754H1 6474H		3V315 6981
917.25570; 917.25580; 917.25590	8833H 5436H	3730 7320	6973
917.25600	8100H 9766H		6979 7355
917.25610; 917.25620	9766H 2295R	7355	6982
917.25630; 917.25631	3754H1 6474H		3V315 6981
917.25640	9766H 2295R	7355	6982
917.25660	130801 148763 144959		6758BR 6702BR 6758BR
917.25700; 917.25701; 917.25710	3350R		6891
917.25720; 917.25721; 917.25722	8833H		6973
917.25723; 917.25730; 917.25731; 917.25732; 917.25733; 917.25734; 917.25740; 917.25741; 917.25742; 917.25743	3754H1 6474H		3V315 6981

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.25744			
Gen. ....	3754H1		3V315
Transaxle .....	6474H	3810	6981
917.25750; 917.25751; 917.25752			
Transaxle .....	2692R		6983
917.25760			
Transaxle .....	3350R		6891
917.25760-1			
Blade .....	6944R		6971
Trans. ....	3350R		6891
917.25761			
Transaxle .....	3350R		6891
917.25770; 917.25780			
Blade .....	6944R		6971
Trans. ....	3350R		6891
917.25781; 917.25782			
Transaxle .....	3350R		6891
917.25790; 917.25792; 917.25793			
Trans. ....	5437R		6851
917.25820; 917.25840; 917.25841; 917.25842; 917.25843			
Blade .....	6944R		6971
Trans. ....	3350R		6891
917.25860; 917.25861; 917.25862; 917.25863; 917.25865; 917.25870; 917.25871; 917.25873; 917.25874			
Trans. ....	6474H		6981
917.25880; 917.25881; 917.25882; 917.25883; 917.25884			
Trans. ....	2692R		6983
917.25920			
Deck .....	131290		6459BR
Drive .....	124525X		6889
917.25921			
Transaxle .....	8833H		6973
917.25930			
Deck .....	131290		6459BR
Drive .....	124525X		6889
917.25940; 917.25941			
Trans. ....	6474H		6981
917.25950			
Trans. ....	2692R		6983
Transaxle .....	67346		6839
917.25951; 917.25960; 917.25961; 917.25963			
Trans. ....	2692R		6983
917.25970; 917.25980			
Trans. ....	5125R		6868
917.57560; 917.57562; 917.57571			
Belt; W/40" Belt O.C. ....	4322M		6840
Reverse .....	7843M	1290	6729
Speed Changer; W/19" Belt O.C. ....	9440M		6819
Speed Changer; W/36" Belt O.C. ....	9441M		6836
917.57583			
Clutch .....	9768M		6840
Reverse .....	7843M	1290	6729
917.57584; 917.57597; 917.57598; 917.57599			
Belt; W/40" Belt O.C. ....	4322M		6840
Reverse .....	7843M	1290	6729
Speed Changer; W/19" Belt O.C. ....	9440M		6819
Speed Changer; W/36" Belt O.C. ....	9441M		6836
917.59101			
Belt; W/45" Belt O.C. ....	8199M		6945
Belt; W/56" Belt O.C. ....	8200M		6956

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.60628; 917.60633; 917.60634; 917.60637; 917.60644; 917.60645; 917.60646			
Eng. To Idler .....	1323H		6970
Gen. ....	3754H		6733
Reverse .....	3496H		6827
Transaxle .....	1322H		6929
917.61201; 917.61202			
Drive; W/35" Belt O.C. ....	2852H		6935
Drive; W/41" Belt O.C. ....	2853H		6941
Drive; W/92" Belt O.C. ....	2851H		6892
917.81320; 917.81360			
Blade .....	55936		6943
917.88010; 917.88011; 917.88020; 917.88021			
Drive; W/35" Belt O.C. ....	2852H		6935
Drive; W/41" Belt O.C. ....	2853H		6941
Drive; W/92" Belt O.C. ....	2851H		6892
917.96270			
Deck .....	59884		6841
Drive .....	58406		6865
917.99400			
Trans. ....	6474H		6981
917.99401			
Gen. ....	3754H1		6733
Trans. ....	6474H		6981
917.99410			
Gen. ....	3754H1		3V315
Transaxle .....	6474H		6981
917.99411			
Gen. ....	3754H1		6733
Trans. ....	6474H		6981
917.99420; 917.99421			
Gen. ....	3754H1		3V315
Transaxle .....	6474H		6981
917.99422			
Gen. ....	3754H1		3V315
Trans. ....	6474H		6981
917.99500			
Gen. ....	3754H1		6733
Trans. ....	5091H		6982
917.99501			
Gen. ....	3754H1		6733
Trans. ....	6474H		6981
917.99510; 917.99511			
Gen. ....	3754H1		6733
Trans. ....	5091H		6982
917.99520; 917.99530			
Gen. ....	3754H1		6733
Trans. ....	6474H		6981
917.99800; 917.99801; 917.99810; 917.99811			
Gen. ....	3754H1		3V315
Transaxle .....	6474H		6981
917.99820			
Gen. ....	3754H1		3V315
Starter/Gen. ....		7320	6981
Transaxle .....	6474H		6981
917.225130			
Trans. ....	73794	2940	6894
917.250020			
Deck .....	106085X		6672BR
Drive .....	123796X		6432BR
917.250030			
Trans. ....	110883X		6899
917.250031			
Drive .....	110883X		6899
917.250032			
Drive .....	110883X		6899





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.250032 – Continued</b>			
Primary .....	110884X		6714BR
Secondary .....	106381X		6892
<b>917.250040</b>			
Deck .....	106085X		6672BR
Drive .....	123796X		6432BR
<b>917.250050; 917.250051</b>			
Drive .....	110883X		6899
<b>917.250260; 917.250261; 917.250262</b>			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	138255		6758BR
<b>917.250270</b>			
Drive .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.250370; 917.250420</b>			
Deck .....	144200		6463BR
Drive .....	160855		6432BR
<b>917.250430; 917.250431; 917.250440</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.250450; 917.250470</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.250480; 917.250481; 917.250482</b>			
Drive .....	137153		6798BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>917.250490; 917.250491</b>			
Drive .....	140218		6811BR
Primary .....	131264		6458BR
Secondary .....	131290		6459BR
<b>917.250510; 917.250550</b>			
Ground Drive .....	137153		6798BR
<b>917.250710; 917.250720; 917.250730</b>			
Blade .....	74164		6851
Trans. ....	67346		6839
<b>917.250740</b>			
Blade .....	67398		6853
Deck .....	74212		6857
Trans. ....	67346		6839
<b>917.250790</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.250810</b>			
Blade .....	59884		6841
<b>917.250830</b>			
Trans. ....	71240		A90
<b>917.250830-1; 917.250831</b>			
Trans. ....	73794	2940	6894
<b>917.251041</b>			
Blade .....	7335H		6845
Main Drive .....	6517H		69100
Mower .....			69100
<b>917.251480</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.251481</b>			
Ground Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.251482</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.251482 – Continued</b>			
Secondary .....	144959		6758BR
<b>917.251490; 917.251491; 917.251492;</b>			
<b>917.251493</b>			
Ground Drive .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.252301</b>			
Starter/Gen. ....	3754H1		3V315
Trans. ....		3790	6979
<b>917.252500; 917.252520; 917.252521</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>917.252530; 917.252531; 917.252532</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.252580</b>			
Deck .....	144200		6463BR
Ground Drive .....	130801		6758BR
<b>917.252630</b>			
Blade .....	7080J		6861
Deck .....	4798J		6878
<b>917.252631</b>			
Mower Deck .....	4798J		6878
Mower Drive .....	7080J		6861
<b>917.252633</b>			
Mower Deck .....	4798J		6878
Mower Drive .....	7080J		6861
Primary Drive .....	4866J		6878
<b>917.252634; 917.252635</b>			
Mower Deck .....	4798J		6878
Mower Drive .....	7080J		6861
<b>917.252640; 917.252641; 917.252643;</b>			
<b>917.252644; 917.252645; 917.252650;</b>			
<b>917.252651; 917.252652; 917.252653;</b>			
<b>917.252654</b>			
Blade .....	7080J		6861
Deck .....	4798J		6878
<b>917.252670; 917.252671; 917.252672;</b>			
<b>917.252673; 917.252674; 917.252680;</b>			
<b>917.252681; 917.252682; 917.252683</b>			
Blade .....	100670N		6879
Primary .....	102726X		6947
<b>917.252702</b>			
Deck .....	518J		6869
Eng. To Trans. ....	1629J		6883
<b>917.252930; 917.252931; 917.252932;</b>			
<b>917.252933</b>			
Blade .....	100670N		6879
Primary .....	102726X		6947
Starter/Gen. ....	3754H1		3V315
Trans. ....		3790	6979
<b>917.253502</b>			
Trans. ....	6474H		6981
<b>917.253710; 917.253711; 917.253712;</b>			
<b>917.253714; 917.253715</b>			
Eng. To Variator .....	7075J		6968
<b>917.253720</b>			
Belt .....	7074J	2650	
<b>917.253740; 917.253740-1; 917.253741;</b>			
<b>917.253742; 917.253742-3; 917.253742-4;</b>			
<b>917.253744; 917.253745</b>			
Drive .....	101342N		6714BR
<b>917.253891</b>			
Blade .....	3703J		68100
Drive .....	110884		6714BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.254170			
Blade .....	4798J		6878
Deck .....	7080J		6861
917.254220			
Blade .....	106085X		6672BR
Trans. ....	105732X		6713BR
917.254221; 917.254230			
Deck .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254231; 917.254232			
Deck .....	106085X		6672BR
917.254240; 917.254241			
Deck .....	37X40		6451BR
Trans. ....	105732X		6713BR
917.254242			
Deck .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254243			
Blade .....	106085X		6672BR
Trans. ....	105732X		6713BR
917.254244; 917.254245			
Blade .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254270; 917.254271; 917.254272			
Blade .....	106085X		6672BR
Drive .....	105732X		6713BR
917.254273; 917.254274; 917.254310; 917.254311; 917.254312			
Blade .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254320			
Blade .....			6879
Trans. ....			6893
917.254321			
Blade .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254322			
Blade .....	106085X		6672BR
917.254330; 917.254331; 917.254332			
Blade .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254350; 917.254360; 917.254361			
Blade .....	106085X		6672BR
Trans. ....	108103X		6881
917.254410			
Blade .....	106381X		6892
Deck .....	106863X		6457BR
Trans. ....	101342N		6714BR
917.254411			
Deck .....	106085X		6672BR
Trans. ....	108103X		6881
917.254412			
Blade .....	106381X		6892
Deck .....	106863X		6457BR
Trans. ....	101342N		6714BR
917.254420; 917.254421			
Blade .....	106381X		6892
Deck .....	106863X		6457BR
Drive .....	110883X		6899
917.254422			
Blade .....	110884X		6714BR
Deck .....	106381X		6892
Trans. ....	110883X		6899
917.254430; 917.254431			
Deck .....	106381X		6892
Drive .....	110883X		6899

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.254432			
Blade .....	110884X		6714BR
Deck .....	106381X		6892
Trans. ....	110883X		6899
917.254440			
Blade .....	106085X		6672BR
Drive; W/81" Belt O.C. ....	108103X		6881
Drive; W/99" Belt O.C. ....	110883X		6899
917.254450			
Blade .....	106085X		6672BR
Drive .....	123796X		6432BR
917.254451			
Deck .....	106085X		6672BR
Drive .....	123796X		6432BR
917.254460			
Blade .....	106085X		6672BR
917.254480			
Blade .....	106085X		6672BR
Deck .....	106381X		6892
Drive; W/81" Belt O.C. ....	108103X		6881
Drive; W/99" Belt O.C. ....	110883X		6899
917.254481			
Blade .....	106085X		6672BR
Drive .....	108103X		6881
917.254490			
Deck; W/100" Belt O.C. ....	3703J		68100
Deck; W/92" Belt O.C. ....	106381X		6892
Trans. ....	110883X		6899
917.254520			
Blade .....	106085X		6672BR
Trans. ....	125907X		6713BR
917.254521; 917.254530			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
917.254531; 917.254532			
Deck .....	131290		6459BR
Drive .....	125907X		6713BR
917.254550; 917.254551; 917.254560			
Blade .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254561			
Deck .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254580			
Blade .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254610			
Blade .....	106085X		6672BR
Trans. ....	125907X		6713BR
917.254611			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
917.254620; 917.254621; 917.254622			
Blade .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254623			
Deck .....	106085X		6672BR
Drive .....	120302X		6713BR
917.254630			
Trans. ....	120302X		6713BR
917.254631; 917.254632; 917.254640; 917.254641; 917.254642			
Blade .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254643			
Deck .....	106085X		6672BR
Drive .....	120302X		6713BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.254650			
Blade .....	106085X		6672BR
Trans. ....	125907X		6713BR
917.254651			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
917.254660; 917.254661; 917.254670			
Blade .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254680			
Blade .....	106085X		6672BR
Trans. ....	108103X		6881
917.254710			
Deck .....	106085X		6672BR
Trans. ....	120302X		6713BR
917.254720			
Blade .....	106085X		6672BR
917.254721			
Deck .....	106085X		6672BR
917.254722			
Blade .....	106085X		6672BR
917.254740			
Blade .....	106085X		6672BR
Trans. ....	108103X		6881
917.254741			
Deck .....	106085X		6672BR
Drive .....	123461X		6881
917.254750			
Deck .....	131290		6459BR
Drive .....	125907X		6713BR
917.254760			
Blade .....	106085X		6672BR
Trans. ....	108103X		6881
917.254780; 917.254790; 917.254791			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
917.254820			
Blade; W/55" Belt O.C. ....	21649		6449BR
Blade; W/79" Belt O.C. ....	106085X		6672BR
Drive .....	20715		6837
Trans. ....	105732X		6713BR
917.254850; 917.254851			
Deck .....	130969		6457BR
Drive .....	130801		6758BR
917.254860; 917.254861			
Deck .....	130969		6457BR
Drive .....	131006		6898
917.254920			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
917.254930			
Blade .....	106085X		6672BR
Trans. ....	125907X		6713BR
917.254940			
Blade .....	37X40		6451BR
917.254941			
Blade .....	106085X		6672BR
Trans. ....	125907X		6713BR
917.254942			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
917.254950			
Blade .....	106085X		6672BR
917.254960			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.254990			
Deck .....	106085X		6672BR
Drive .....	126576X		6882
917.255020			
Blade .....	106085X		6672BR
917.255120			
Blade .....	518J		6869
Trans. ....	543J		6867
917.255121			
Blade .....	518J		6869
Drive .....	5125R		6868
917.255131			
Blade .....	518J		6869
Trans. ....	73794	2940	6894
917.255260			
Blade .....	518J		6869
Drive .....	543J		6867
917.255270			
Blade .....	518J		6869
Drive .....	1629J		6883
917.255270-1; 917.255270-2; 917.255270-3; 917.255270-4; 917.255270-5; 917.255270-6; 917.255270-7; 917.255270-8; 917.255270-9			
Deck .....	518J		6869
Eng. To Trans. ....	1629J		6883
917.255271			
Blade .....	518J		6869
Drive .....	1629J		6883
917.255272; 917.255273; 917.255274; 917.255275; 917.255276			
Deck .....	518J		6869
Eng. To Trans. ....	1629J		6883
917.255277			
Blade .....	100717N		6869
Traction .....			6883
917.255278			
Deck .....	518J		6869
Eng. To Trans. ....	1629J		6883
917.255279			
Blade .....	100717N		6869
Traction .....			6883
917.255330			
Trans. ....	73794	2940	6894
917.255340; 917.255350			
Blade .....	518J		6869
917.255370			
Blade .....	100717N		6869
Traction .....			6883
917.255370-1			
Trans. ....	1629J		6883
917.255371; 917.255372			
Blade .....	100717N		6869
Traction .....			6883
917.255373			
Trans. ....	1629J		6883
917.255410			
Blade .....	518J		6869
Traction .....	543J		6867
Trans. ....	120302X		6713BR
917.255411			
Blade .....	518J		6869
Trans. ....	543J		6867
917.255412			
Blade .....	100717N		6869
Traction .....	543J		6867

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.255413</b>			
Blade .....	518J		6869
Trans. ....	543J		6867
<b>917.255414</b>			
Blade .....	100717N		6869
Traction .....	543J		6867
<b>917.255415</b>			
Blade .....	518J		6869
Trans. ....	543J		6867
<b>917.255416</b>			
Traction .....	543J		6867
<b>917.255417</b>			
Eng. To Variator .....	177J		6943
Variator To Trans. ....	178J		6952
<b>917.255510; 917.255520</b>			
Blade .....	106085X		6672BR
Trans. ....	125907X		6713BR
<b>917.255590</b>			
Deck .....	131290		6459BR
Drive .....	126576X		6882
<b>917.255701; 917.255702; 917.255703; 917.255704</b>			
Trans. ....	1629J		6883
<b>917.255720</b>			
Blade .....	106085X		6672BR
Deck .....	100670N		6879
Trans. ....	105732X		6713BR
<b>917.255722; 917.255723; 917.255724; 917.255725; 917.255726; 917.255727; 917.255730; 917.255732; 917.255733; 917.255734</b>			
Blade .....	106085X		6672BR
Trans. ....	105732X		6713BR
<b>917.255735; 917.255736; 917.255740; 917.255741; 917.255742</b>			
Blade .....	106085X		6672BR
Trans. ....	105732X		6713BR
<b>917.255810</b>			
Blade .....	106085X		6672BR
Deck .....	100670N		6879
Trans. ....	105732X		6713BR
<b>917.255812; 917.255813</b>			
Blade .....	106085X		6672BR
Trans. ....	105732X		6713BR
<b>917.255820</b>			
Blade .....	100670N		6879
Trans. ....	105876X		6893
<b>917.255821; 917.255822</b>			
Blade .....	106085X		6672BR
Trans. ....	105876X		6893
<b>917.255830; 917.255831</b>			
Blade .....	106085X		6672BR
Trans. ....	120302X		6713BR
<b>917.255850</b>			
Blade .....	106085X		6672BR
Trans. ....	108103X		6881
<b>917.255910</b>			
Blade .....	106381X		6892
Drive; W/93" Belt O.C. ....	101342N		6714BR
Drive; W/99" Belt O.C. ....	110883X		6899
<b>917.255911</b>			
Blade .....	106381X		6892
Trans. ....	101342N		6714BR
<b>917.255912</b>			
Blade .....	106381X		6892
Deck .....	106863X		6457BR
Drive .....	101342N		6714BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.255913</b>			
Blade .....	106381X		6892
Deck .....	106863X		6457BR
Trans. ....	101342N		6714BR
<b>917.255914</b>			
Blade .....	106381X		6892
Deck .....	110884X		6714BR
Trans. ....	110883X		6899
<b>917.255915</b>			
Blade .....	106381X		6892
Deck .....	106863X		6457BR
Drive .....	101342N		6714BR
<b>917.255916; 917.255917; 917.255918</b>			
Blade .....	106381X		6892
Deck .....	110884X		6714BR
Trans. ....	110883X		6899
<b>917.255920</b>			
Drive .....	123796X		6432BR
<b>917.255930; 917.255934; 917.255935; 917.255950; 917.255960; 917.255961</b>			
Blade .....	106381X		6892
Deck .....	110884X		6714BR
Trans. ....	110883X		6899
<b>917.256220; 917.256230; 917.256240</b>			
Blade .....	124293X		6880
Traction .....	124525X		6889
<b>917.256320; 917.256321; 917.256322</b>			
Deck .....	124293X		6880
Drive .....	126520X		6459BR
<b>917.256350; 917.256360</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.256370; 917.256380</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.256390</b>			
Deck .....	144200		6463BR
Drive .....	141416		6444BR
<b>917.256410; 917.256420; 917.256421</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.256430</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.256450; 917.256451; 917.256460</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.256490; 917.256491</b>			
Deck .....	144200		6463BR
Drive .....	141416		6444BR
<b>917.256500; 917.256501; 917.256510; 917.256511; 917.256521; 917.256522; 917.256523; 917.256524</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.256530; 917.256531; 917.256532</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.256540; 917.256541; 917.256542; 917.256543; 917.256544; 917.256545</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.256550; 917.256551; 917.256552; 917.256553</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.256560; 917.256561; 917.256562;</b>			
<b>917.256563</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.256570; 917.256571</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.256580; 917.256581; 917.256582;</b>			
<b>917.256583</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.256590; 917.256591</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.256600; 917.256601</b>			
Drive .....	130801		6758BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.256610; 917.256611</b>			
Drive .....	140294		6434BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.256660; 917.256661</b>			
Drive .....	130801		6758BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.256662</b>			
Drive .....	130801		6758BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.256670</b>			
Drive .....	140294		6434BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.256680</b>			
Drive .....	130801		6758BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.256690</b>			
Drive .....	140294		6434BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.256700; 917.256701; 917.256702</b>			
Drive .....	130801		6758BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.256710; 917.256711; 917.256712</b>			
Drive .....	140294		6434BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.256810; 917.256811; 917.256812</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.256820</b>			
Deck .....	131264		6458BR
Drive .....	124525X		6889
<b>917.256830</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.256850; 917.256851</b>			
Deck .....	131290		6459BR
Drive .....	124525X		6889
<b>917.256870</b>			
Deck .....	144200		6463BR
Drive .....	141416		6444BR
<b>917.256880; 917.256881</b>			
Deck .....	131290		6459BR
Drive .....	124525X		6889

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.256890; 917.256891</b>			
Deck .....	144200		6463BR
Drive .....	141416		6444BR
<b>917.256920</b>			
Deck .....	131290		6459BR
Drive .....	124525X		6889
<b>917.256921</b>			
Deck .....	131290		6459BR
Drive .....	126520X		6459BR
<b>917.256922; 917.256930</b>			
Deck .....	131290		6459BR
Drive .....	124525X		6889
<b>917.257020; 917.257021; 917.257030</b>			
Primary Trans. ....	177J		6943
Secondary Trans. ....	178J		6952
<b>917.257031; 917.257032</b>			
Deck .....	9121R		A112
Primary Trans. ....	177J		6943
Secondary Trans. ....	178J		6952
<b>917.257050; 917.257060; 917.257061</b>			
Trans. ....	2692R		6983
<b>917.257070</b>			
Trans. ....	5125R		6868
<b>917.257080; 917.257081; 917.257082</b>			
Drive .....	2692R		6983
Trans. ....	2692R		6983
<b>917.257090; 917.257091</b>			
Primary Trans. ....	177J		6943
Secondary Trans. ....	178J		6952
<b>917.257110; 917.257111; 917.257112;</b>			
<b>917.257114; 917.257120; 917.257130</b>			
Trans. ....	2692R		6983
<b>917.257210; 917.257211; 917.257280;</b>			
<b>917.257281; 917.257290</b>			
Deck .....	131290		6459BR
Drive .....	125907X		6713BR
<b>917.257350</b>			
Blade .....	106085X		6672BR
Trans. ....	125907X		6713BR
<b>917.257360</b>			
Blade .....	106085X		6672BR
<b>917.257460</b>			
Deck .....	124293X		6880
Drive .....	124525X		6889
<b>917.257470; 917.257480</b>			
Blade .....	106085X		6672BR
Trans. ....	125907X		6713BR
<b>917.257481</b>			
Deck .....	106085X		6672BR
Drive .....	125907X		6713BR
<b>917.257550</b>			
Deck .....	140067		6551BR
Drive .....	130801		6758BR
<b>917.257551; 917.257552</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.257560</b>			
Deck .....	130969		6757BR
Drive .....	130801		6758BR
<b>917.257561</b>			
Deck .....	140067		6551BR
Drive .....	130801		6758BR
<b>917.257562; 917.257563</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>				<b>SEARS ROEBUCK - Continued</b>			
917.257570; 917.257571				917.258020; 917.258021 - Continued			
Deck ..... 130969			6757BR	Drive ..... 130801			6758BR
Drive ..... 130801			6758BR				
917.257572				917.258030			
Deck ..... 140067			6551BR	Deck ..... 144200			6463BR
Drive ..... 130801			6758BR	Drive ..... 140294			6434BR
917.257573				917.258031			
Deck ..... 144200			6463BR	Deck ..... 144959			6758BR
Drive ..... 130801			6758BR	Drive ..... 140294			6434BR
917.257590				917.258050; 917.258051; 917.258070;			
Deck ..... 140067			6551BR	917.258071; 917.258072			
Drive ..... 140294			6434BR	Deck ..... 144200			6463BR
917.257591				Drive ..... 130801			6758BR
Deck ..... 140067			6551BR	917.258080			
Drive ..... 141416			6444BR	Deck ..... 144200			6463BR
917.257592				Drive ..... 156971			6558BR
Deck ..... 144200			6463BR	917.258081			
Drive ..... 141416			6444BR	Deck ..... 144959			6758BR
917.257620				Drive ..... 141416			6444BR
Deck ..... 131290			6459BR	917.258082			
Drive ..... 138255			6758BR	Deck ..... 144200			6463BR
917.257621				Drive ..... 141416			6444BR
Deck ..... 126520X			6459BR	917.258100			
Drive ..... 130801			6758BR	Deck ..... 144200			6463BR
917.257630				Drive ..... 130801			6758BR
Deck ..... 138255			6758BR	917.258101			
Drive ..... 130969			6757BR	Deck ..... 144959			6758BR
917.257631				Drive ..... 130801			6758BR
Deck ..... 140067			6551BR	917.258102; 917.258103; 917.258110			
Drive ..... 130801			6758BR	Deck ..... 144200			6463BR
917.257640				Drive ..... 130801			6758BR
Deck ..... 130969			6757BR	917.258111			
Drive ..... 138255			6758BR	Deck ..... 144959			6758BR
917.257641				Drive ..... 130801			6758BR
Deck ..... 130969			6757BR	917.258112; 917.258113			
Drive ..... 130801			6758BR	Deck ..... 144200			6463BR
917.257642; 917.257643				Drive ..... 130801			6758BR
Deck ..... 140067			6551BR	917.258140			
Drive ..... 130801			6758BR	Deck ..... 124525X			6889
917.257644; 917.257650; 917.257652;				Drive ..... 124293X			6880
917.257653				917.258160			
Deck ..... 144200			6463BR	Deck ..... 144200			6463BR
Drive ..... 130801			6758BR	Drive ..... 130801			6758BR
917.257660				917.258161			
Deck ..... 140067			6551BR	Deck ..... 144959			6758BR
Drive ..... 140294			6882	Drive ..... 130801			6758BR
917.257661				917.258170			
Deck ..... 144200			6463BR	Deck ..... 144200			6463BR
Drive ..... 140294			6434BR	Drive ..... 140294			6434BR
917.257690				917.258171			
Deck ..... 130969			6757BR	Deck ..... 144959			6758BR
Drive ..... 140294			6434BR	Drive ..... 140294			6434BR
917.257710; 917.257711; 917.257720;				917.258172			
917.257721				Deck ..... 144200			6463BR
Drive ..... 137153			6798BR	Drive ..... 140294			6434BR
Primary ..... 131264			6458BR	917.258260; 917.258261			
Secondary ..... 131290			6459BR	Drive ..... 130801			6758BR
917.257730; 917.257731				Primary ..... 158818			6444BR
Drive ..... 140218			6811BR	Secondary ..... 144959			6758BR
Primary ..... 131264			6458BR	917.258270; 917.258271			
Secondary ..... 131290			6459BR	Drive ..... 140294			6434BR
917.257740				Primary ..... 158818			6444BR
Drive ..... 137153			6798BR	Secondary ..... 144959			6758BR
Primary ..... 139573			6798BR	917.258331			
Secondary ..... 138255			6758BR	Deck ..... 140294			6434BR
917.258020; 917.258021				Drive ..... 140294			6434BR
Deck ..... 144200			6463BR				



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.258440			
Deck .....	165555		6579BR
Drive .....	165632		6928BR
917.258450; 917.258451; 917.258452; 917.258470; 917.258471; 917.258472; 917.258473			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
917.258480			
Deck .....	144200		6463BR
Drive .....	141416		6444BR
917.258481			
Deck .....	144959		6758BR
Drive .....	141416		6444BR
917.258482			
Deck .....	144200		6463BR
Drive .....	141416		6444BR
917.258491; 917.258492; 917.258493; 917.258494			
Deck .....	130969		6457BR
Drive .....	131006		6898
917.258500; 917.258501; 917.258502; 917.258503; 917.258504; 917.258510; 917.258512; 917.258513; 917.258514; 917.258515			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
917.258516; 917.258520			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
917.258521			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
917.258522			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
917.258523			
Deck .....	144200		6463BR
Drive .....	160855		6432BR
917.258524			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
917.258530			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
917.258531			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
917.258532; 917.258534			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
917.258535			
Deck .....	144200		6463BR
Drive .....	156971		6558BR
917.258540; 917.258541; 917.258542; 917.258543			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
917.258544			
Deck .....	144200		6463BR
Drive .....	160855		6432BR
917.258550			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
917.258551			
Deck .....	144959		6758BR
Drive .....	140294		6434BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.258553			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
917.258555			
Deck .....	144200		6463BR
Drive .....	156971		6558BR
917.258557			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
917.258560; 917.258561; 917.258563; 917.258564			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
917.258565; 917.258566			
Deck .....	144200		6463BR
Drive .....	160855		6432BR
917.258570; 917.258572; 917.258573			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
917.258580; 917.258581			
Drive .....	130801		6758BR
Primary .....	158818		6444BR
Secondary .....	144959		6758BR
917.258590; 917.258591; 917.258592			
Drive .....	140294		6434BR
Primary .....	158818		6444BR
Secondary .....	144959		6758BR
917.258600; 917.258602; 917.258603			
Drive .....	130801		6758BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
917.258670; 917.258671; 917.258672; 917.258673			
Drive .....	140294		6434BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
917.258680; 917.258681; 917.258682			
Drive .....	130801		6758BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
917.258683; 917.258684; 917.258685			
Drive .....	160855		6432BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
917.258690; 917.258691; 917.258692; 917.258693; 917.258694			
Drive .....	140294		6434BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
917.258695			
Drive .....	161588		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
917.258780			
Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
917.258790			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
917.258860			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
917.258861			
Drive .....	137153		6798BR
Primary .....	139573		6883
Secondary .....	144959		6758BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.258862; 917.258863</b>			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.258870; 917.258871; 917.258872; 917.258873</b>			
Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.258880; 917.258881</b>			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.258890; 917.258891</b>			
Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.258900; 917.258901; 917.258902; 917.258903; 917.258904</b>			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.258910; 917.258911; 917.258912; 917.258913; 917.258914; 917.258920; 917.258921; 917.258922</b>			
Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.258940</b>			
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.258960; 917.258961; 917.258962</b>			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.258970; 917.258971; 917.258972; 917.258973</b>			
Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.258980</b>			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.258990</b>			
Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.259180; 917.259250</b>			
Trans .....	67346		6839
<b>917.259270</b>			
Blade .....	106085X		6672BR
Trans .....	125907X		6713BR
<b>917.259320</b>			
Trans .....	67346		6839
<b>917.259470</b>			
Blade .....	67398		6853
Deck .....	74212		6857
Trans .....	67346		6839
<b>917.259560; 917.259564</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.259565; 917.259566; 917.259567</b>			
Deck .....	144200		6463BR
Drive .....	160855		6432BR
<b>917.259730</b>			
Blade .....	106085X		6672BR
Trans .....	125907X		6713BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.270530; 917.270670</b>			
Deck Drive .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.270681</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.270760</b>			
Drive .....	140294		6434BR
<b>917.270930</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271010; 917.271011; 917.271012</b>			
Deck .....	144200		6463BR
Drive .....	160855		6432BR
<b>917.271013; 917.271014</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.271020</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.271021</b>			
Deck .....	144200		6463BR
Drive .....	161588		6798BR
<b>917.271022; 917.271023; 917.271024</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.271030</b>			
Deck .....	144200		6463BR
Drive .....	160855		6432BR
<b>917.271031</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.271040</b>			
Deck .....	144200		6463BR
Drive .....	161588		6798BR
<b>917.271041; 917.271042</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.271050</b>			
Deck .....			6895
Drive .....			6895
<b>917.271051; 917.271052; 917.271053; 917.271054</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271060; 917.271061; 917.271062; 917.271063; 917.271064</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.271070</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.271071; 917.271072</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271080</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.271090</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.271100</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.271110</b>			
Deck .....	144200		6463BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.271110 – Continued</b>			
Drive .....	160855		6432BR
<b>917.271111</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>917.271120</b>			
Deck .....	144200		6463BR
Drive .....	161588		6798BR
<b>917.271121</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.271130</b>			
Deck .....			6895
Drive .....			6895
<b>917.271131; 917.271132; 917.271133</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271140; 917.271141; 917.271142</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.271150</b>			
Deck .....	144200		6463BR
Drive .....	160855		6432BR
<b>917.271380</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>917.271470; 917.271490; 917.271491</b>			
Deck .....	144200		6463BR
Drive .....	160855		6432BR
<b>917.271530</b>			
Deck .....			6895
<b>917.271531; 917.271532</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.271550</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271551</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.271552</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271553</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.271554</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271555</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.271630</b>			
Deck .....			6895
<b>917.271631; 917.271632; 917.271633;</b>			
<b>917.271634; 917.271635</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.271640</b>			
Deck .....			6895
<b>917.271641; 917.271642; 917.271643</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.271644</b>			
Deck .....	144959		6758BR
Drive .....	178138		6627BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.271645</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.271650</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271651; 917.271652; 917.271653</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.271654</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271730</b>			
Deck .....			6895
Drive .....			6895
<b>917.271731; 917.271732; 917.271733;</b>			
<b>917.271734</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271740</b>			
Deck .....			6895
<b>917.271742; 917.271743</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.271744</b>			
Deck .....	144959		6758BR
Drive .....	178138		6627BR
<b>917.271750; 917.271810; 917.271811;</b>			
<b>917.271812; 917.271813; 917.271814</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271820; 917.271821; 917.271822;</b>			
<b>917.271823; 917.271825; 917.271826</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.271830</b>			
Deck .....			6895
Drive .....			6895
<b>917.271831; 917.271832</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271840</b>			
Deck .....			6895
<b>917.271841; 917.271842</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.271850; 917.271851; 917.271910</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.271920</b>			
Deck .....	144959		6758BR
Ground Drive .....	140294		6434BR
<b>917.272010; 917.272011</b>			
Drive .....	160855		6432BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.272020</b>			
Drive .....	161588		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.272021</b>			
Ground Drive .....	140294		6434BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.272030</b>			
Drive .....	130801		6758BR
Primary .....	148763		6702BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.272030 – Continued</b>			
Secondary .....	144959		6758BR
<b>917.272040</b>			
Drive .....	140294	6434BR	
Primary .....	148763	6702BR	
Secondary .....	144959	6758BR	
<b>917.272050; 917.272051; 917.272052;</b>			
<b>917.272053; 917.272054; 917.272055;</b>			
<b>917.272056; 917.272057; 917.272058;</b>			
<b>917.272059</b>			
Deck .....	144959	6758BR	
Drive .....	130801	6758BR	
<b>917.272060; 917.272061; 917.272063;</b>			
<b>917.272064; 917.272065; 917.272066;</b>			
<b>917.272067; 917.272068; 917.272069</b>			
Deck .....	144959	6758BR	
Drive .....	140294	6434BR	
<b>917.272070; 917.272072; 917.272073;</b>			
<b>917.272074; 917.272075</b>			
Deck .....	144959	6758BR	
Drive .....	130801	6758BR	
<b>917.272080; 917.272081; 917.272082;</b>			
<b>917.272083; 917.272084</b>			
Deck .....	144959	6758BR	
Drive .....	140294	6434BR	
<b>917.272120</b>			
Drive .....	161588	6798BR	
Primary .....	139573	6798BR	
Secondary .....	144959	6758BR	
<b>917.272121</b>			
Drive .....	140294	6434BR	
Primary .....	139573	6798BR	
Secondary .....	144959	6758BR	
<b>917.272130</b>			
Drive .....	130801	6758BR	
Primary .....	148763	6702BR	
Secondary .....	144959	6758BR	
<b>917.272140</b>			
Drive .....	140294	6434BR	
Primary .....	148763	6702BR	
Secondary .....	144959	6758BR	
<b>917.272150</b>			
Drive .....	130801	6758BR	
Primary .....	148763	6702BR	
Secondary .....	144959	6758BR	
<b>917.272160</b>			
Drive .....	140294	6434BR	
Primary .....	148763	6702BR	
Secondary .....	144959	6758BR	
<b>917.272190</b>			
Drive .....	130801	6758BR	
Primary .....	148763	6702BR	
Secondary .....	144959	6758BR	
<b>917.272200; 917.272201; 917.272202</b>			
Drive .....	140294	6434BR	
Primary .....	148763	6702BR	
Secondary .....	144959	6758BR	
<b>917.272220</b>			
Deck .....	144959	6758BR	
Drive .....	140294	6434BR	
<b>917.272230; 917.272231; 917.272232;</b>			
<b>917.272233; 917.272234</b>			
Drive .....	130801	6758BR	
Primary .....	174368	6649BR	
Secondary .....	174369	6614BR	
<b>917.272240; 917.272241; 917.272242;</b>			
<b>917.272243; 917.272244; 917.272245 –</b>			
<b>Continued</b>			
Primary .....	174368		6649BR
Secondary .....	174369		6614BR
<b>917.272246</b>			
Ground Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.272247; 917.272248</b>			
Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.272260</b>			
Ground Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	174369		6614BR
<b>917.272261; 917.272262; 917.272263</b>			
Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	174369		6614BR
<b>917.272264; 917.272265</b>			
Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.272280</b>			
Deck .....	174883		6721BR
Ground Drive .....	140294		6434BR
<b>917.272281; 917.272282</b>			
Deck .....	174883		6721BR
Drive .....	140294		6434BR
<b>917.272350</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.272351</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272352</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.272410</b>			
Deck .....	174883		6721BR
Drive .....	130801		6758BR
<b>917.272420; 917.272421</b>			
Deck .....	174883		6721BR
Drive .....	140294		6434BR
<b>917.272430; 917.272431; 917.272432</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272440; 917.272441; 917.272442</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.272450</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>917.272451</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272452</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>917.272453; 917.272454</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272480; 917.272481</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.272240; 917.272241; 917.272242;</b>			
<b>917.272243; 917.272244; 917.272245 –</b>			
<b>Continued</b>			
Primary .....	174368		6649BR
Secondary .....	174369		6614BR
<b>917.272246</b>			
Ground Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.272247; 917.272248</b>			
Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.272260</b>			
Ground Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	174369		6614BR
<b>917.272261; 917.272262; 917.272263</b>			
Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	174369		6614BR
<b>917.272264; 917.272265</b>			
Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.272280</b>			
Deck .....	174883		6721BR
Ground Drive .....	140294		6434BR
<b>917.272281; 917.272282</b>			
Deck .....	174883		6721BR
Drive .....	140294		6434BR
<b>917.272350</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.272351</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272352</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.272410</b>			
Deck .....	174883		6721BR
Drive .....	130801		6758BR
<b>917.272420; 917.272421</b>			
Deck .....	174883		6721BR
Drive .....	140294		6434BR
<b>917.272430; 917.272431; 917.272432</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272440; 917.272441; 917.272442</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.272450</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>917.272451</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272452</b>			
Deck .....	144959		6758BR
Ground Drive .....	130801		6758BR
<b>917.272453; 917.272454</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272480; 917.272481</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.272650</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272660</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.272670</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.272671</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272672</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.272673; 917.272674</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272680; 917.272681</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.272751; 917.272754; 917.272759</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272760; 917.272761; 917.272762</b>			
Deck .....	144959		6758BR
Drive .....	178138		6627BR
<b>917.272850; 917.272851</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272860; 917.272861; 917.272862</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.272910; 917.272911; 917.272912</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.272920; 917.272921; 917.272922</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.272950; 917.272951; 917.272952; 917.272953; 917.272954; 917.272955</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.272960; 917.272961</b>			
Drive .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.272962</b>			
Deck .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.273010; 917.273011</b>			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.273012; 917.273013; 917.273014</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.273020; 917.273021</b>			
Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.273022; 917.273023</b>			
Drive .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.273030</b>			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.273031</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.273040; 917.273041</b>			
Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.273042</b>			
Drive .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.273050; 917.273051; 917.273052</b>			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.273060; 917.273061; 917.273062; 917.273064</b>			
Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.273070</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.273080</b>			
Drive .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.273090</b>			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.273100</b>			
Drive .....			6885
Primary .....			6883
Secondary .....			6895
<b>917.273130; 917.273131; 917.273134; 917.273135</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273140; 917.273142</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273150</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273160; 917.273180</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273240; 917.273241; 917.273280; 917.273281</b>			
Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.273350; 917.273351</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.273360</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273370; 917.273371</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR

Lawn & Garden Equipment

RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.273372</b>			
Deck .....	144959		6758BR
Drive .....	160855		6758BR
<b>917.273373</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.273374</b>			
Deck .....	144959		6758BR
<b>917.273380</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273383</b>			
Deck .....	144959		6758BR
Drive .....	178138		6627BR
<b>917.273390</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273391</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.273392; 917.273393; 917.273394</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273400</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273401</b>			
Deck .....	144959		6758BR
Drive .....	178138		6627BR
<b>917.273450; 917.273451</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273460; 917.273461</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273470; 917.273471</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273480; 917.273481; 917.273482</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273490</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273500; 917.273502</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273510</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273512</b>			
Deck .....	144959		6758BR
Drive .....	160855		6758BR
<b>917.273513</b>			
Deck .....	144959		6758BR
Drive .....	160855		6432BR
<b>917.273520</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273521; 917.273522</b>			
Deck .....	144959		6758BR
Drive .....	178138		6627BR
<b>917.273610; 917.273611</b>			
Drive .....	130801		6758BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.273620; 917.273621</b>			
Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.273630</b>			
Deck .....	174883		6721BR
Drive .....	130801		6758BR
<b>917.273631</b>			
Deck .....	174883		6721BR
Drive .....	160855		6432BR
<b>917.273632; 917.273634</b>			
Deck .....	174883		6721BR
Drive .....	130801		6758BR
<b>917.273640; 917.273641; 917.273642; 917.273643</b>			
Deck .....	174883		6721BR
Drive .....	140294		6434BR
<b>917.273661; 917.273662; 917.273663</b>			
Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.273750; 917.273751</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273760; 917.273761</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273770</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273780</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273790</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273800</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.273810</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.273820</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.274350</b>			
Deck Drive .....	144959		6758BR
Drive .....	138255		6758BR
<b>917.274400</b>			
Deck Drive .....	144959		6758BR
Drive .....	178138		6627BR
<b>917.274630</b>			
Deck Drive .....	174883		6721BR
Drive .....	138255		6758BR
<b>917.274640</b>			
Deck Drive .....	174883		6721BR
Drive .....	178138		6627BR
<b>917.274820</b>			
Deck Drive .....	144959		6758BR
Drive .....	178138		6627BR
<b>917.274950</b>			
Drive .....	137153		6798BR
Primary .....			6986
Secondary .....			6895
<b>917.274960</b>			
Primary .....			6986
Secondary .....			6895



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.274970</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.275000</b>			
Drive .....	161597		6551BR
<b>917.275010; 917.275011</b>			
Drive .....	137153		6798BR
Primary .....	174368		6649BR
Secondary .....	174369		6614BR
<b>917.275012; 917.275013</b>			
Drive .....	137153		6798BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.275020; 917.275021</b>			
Drive .....	161597		6551BR
Primary .....	174368		6649BR
Secondary .....	174369		6614BR
<b>917.275022; 917.275023</b>			
Drive .....	161597		6551BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.275030; 917.275031</b>			
Drive .....	137153		6798BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.275032; 917.275033; 917.275034</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.275040; 917.275041; 917.275042</b>			
Drive .....	161597		6551BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>917.275043; 917.275044</b>			
Drive .....	161597		6551BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.275180</b>			
Deck Drive .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.275221; 917.275222; 917.275223</b>			
Drive .....	161597		6551BR
Primary .....	174368		6649BR
Secondary .....	174369		6614BR
<b>917.275240</b>			
Drive .....			6885
<b>917.275241; 917.275242</b>			
Drive .....	161597		6551BR
Primary .....	174368		6649BR
Secondary .....	174369		6614BR
<b>917.275280; 917.275281; 917.275282;</b>			
<b>917.275283; 917.275284; 917.275285;</b>			
<b>917.275286; 917.275287</b>			
Drive .....	161597		6551BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.275370</b>			
Deck Drive .....	144959		6758BR
Drive .....	138255		6758BR
<b>917.275400; 917.275520</b>			
Deck Drive .....	144959		6758BR
Drive .....	178138		6627BR
<b>917.275630</b>			
Deck Drive .....	174883		6721BR
Drive .....	138255		6758BR
<b>917.275750</b>			
Deck Drive .....	144959		6758BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.275750 - Continued</b>			
Drive .....	138255		6758BR
<b>917.275760</b>			
Deck Drive .....	144959		6758BR
Drive .....	178138		6627BR
<b>917.275810</b>			
Deck Drive .....	144959		6758BR
Drive .....	138255		6758BR
<b>917.275820</b>			
Deck Drive .....	144959		6758BR
Drive .....	178138		6627BR
<b>917.275900</b>			
Drive .....	140294		6434BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.275970; 917.275971; 917.275972</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.276010; 917.276011; 917.276013</b>			
Drive .....	137153		6798BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.276020; 917.276021</b>			
Drive .....	161597		6551BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.276030</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.276040; 917.276041</b>			
Drive .....	161597		6551BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.276050</b>			
Drive .....	137153		6798BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>917.276070</b>			
Drive .....	137153		6798BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.276081</b>			
Drive .....	161597		6551BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.276120</b>			
Deck .....	191273		6599BR
<b>917.276210</b>			
Deck Drive .....	191273		6599BR
Drive .....	137153		6798BR
<b>917.276220</b>			
Deck Drive .....	191273		6599BR
Drive .....	161597		6551BR
<b>917.276230</b>			
Deck Drive .....	191273		6599BR
Drive .....	137153		6798BR
<b>917.276310</b>			
Drive .....	137153		6798BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.276320</b>			
Drive .....	161597		6551BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.276330</b>			
Deck Drive .....	191273		6599BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.276330 – Continued</b>			
Drive .....	137153		6798BR
<b>917.276340</b>			
Deck Drive .....	191273		6599BR
Drive .....	161597		6551BR
<b>917.276350</b>			
Drive .....	137153		6798BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.276360</b>			
Drive .....	161597		6551BR
Primary .....	174368		6649BR
Secondary .....	180808		6614BR
<b>917.276380</b>			
Deck Drive .....	191273		6599BR
Drive .....	161597		6551BR
<b>917.279370; 917.279870; 917.279871;</b>			
<b>917.279872</b>			
Deck .....	144959		6758BR
Drive .....	130801		6758BR
<b>917.380280</b>			
Blade .....	106085X		6672BR
<b>917.575100</b>			
Clutch .....	9768M		6840
Reverse .....	7843M	1290	6729
<b>917.575102; 917.575104; 917.575119</b>			
Belt; W/40" Belt O.C. ....	4322M		6840
Reverse .....	7843M	1290	6729
Speed Changer; W/19" Belt O.C. ....	9440M		6819
Speed Changer; W/36" Belt O.C. ....	9441M		6836
<b>917.575120</b>			
Clutch .....	9768M		6840
Reverse .....	7843M	1290	6729
<b>917.575131</b>			
Belt; W/40" Belt O.C. ....	4322M		6840
Reverse .....	7843M	1290	6729
Speed Changer; W/19" Belt O.C. ....	9440M		6819
Speed Changer; W/36" Belt O.C. ....	9441M		6836
<b>917.606029; 917.606030; 917.606044;</b>			
<b>917.606045; 917.606046</b>			
Eng. To Idler .....	1323H		6970
Gen. ....	3754H		6733
Reverse .....	3496H		6827
Transaxle .....	1322H		6929
<b>917.608151; 917.608201; 917.608501</b>			
Drive .....	2692R		6983
Trans. ....	2692R		6983
<b>917.2552701; 917.2552702</b>			
Blade .....	100717N		6869
Traction .....			6883
<b>917.2552702-3; 917.2552702-4; 917.2552703;</b>			
<b>917.2552704</b>			
Trans. ....	1629J		6883
<b>917.2559101</b>			
Blade .....	110884X		6714BR
Trans. ....	110883X		6899
<b>917.2575112</b>			
Belt; W/23" Belt O.C. ....	529H	3230	
Belt; W/38" Belt O.C. ....	530H		B35
<b>917.2720601</b>			
Deck .....	144959		6758BR
Drive .....	140294		6434BR
<b>917.6060028</b>			
Eng. To Idler .....	1323H		6970
Gen. ....	3754H		6733
Reverse .....	3496H		6827
Transaxle .....	1322H		6929

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>917.7256010</b>			
Blade .....	20717		6856
Drive .....	20716		6837
<b>926.55550; 926.55560</b>			
Eng. To Center Spindle .....	SA801		6986
Eng. To Variable Speed .....	SA804		6925
J.S. To Variable Speed .....	SA975		6941
Spindle - Center To Side .....			6842
<b>926.55580; 926.55590</b>			
Drive .....	SA800		B105
Eng. To Variable Speed .....	SA804		6925
Rear Drive .....	SA803		6942
Side Pulleys .....	M60		6953
<b>926.55750; 926.55751; 926.55752</b>			
Belt; W/30" Belt O.C. ....	M425C		6830
Belt; W/42" Belt O.C. ....			6842
Belt; W/45" Belt O.C. ....	M426C		6845
<b>944.609040</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>944.609810</b>			
Drive .....	140294		6434BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>944.609900</b>			
Drive .....	140218		6811BR
Primary .....	148763		6702BR
Secondary .....	144959		6758BR
<b>944.609940</b>			
Drive .....	140218		6811BR
Primary .....	139573		6798BR
Secondary .....	144959		6758BR
<b>987.25942</b>			
Drive .....	1747188		6897
<b>987.25943</b>			
Drive .....	1751597		6891
<b>987.25944</b>			
Drive .....	1747188		6897
<b>987.25945</b>			
Drive .....	1751597		6891
<b>25990</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>25992</b>			
Deck .....	144200		6463BR
Drive .....	156971		6558BR
<b>25993</b>			
Deck .....	144200		6463BR
Drive .....	140294		6434BR
<b>25995; 25996</b>			
Deck .....	144200		6463BR
Drive .....	130801		6758BR
<b>LT 10</b>			
Blade .....	23223		6895
Drive .....	23214		6859
Trans. ....	21615		6895
<b>LT 80</b>			
Deck; W/8 H.P. Eng. ....	3541R		6971
<b>SS 16</b>			
Trans.; W/16 H.P. Eng. ....	2692R		6983
<b>ST 8</b>			
Drive .....	21053		6862
Trans. ....	23072		6843
<b>ST 12</b>			
Trans.; W/12 H.P. Eng. ....	6474H		6981



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>ST 16</b>			
Blade .....	6774H		6981
Trans. ....			B100
<b>SENSATION</b>			
<b>80E8-1; 80E8-2; 80S8-1; 80S8-2; 86S5-1; 86S5-2</b>			
Belt; W/34" Belt O.C. ....	153801		6834
Belt; W/70" Belt O.C. ....	153802		6870
<b>SENTRY</b>			
<b>330-6</b>			
Belt; W/30" Belt O.C. ....	7540107		6830
<b>340-6; 340-7; 360-5; 360-7; 360-8</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936		6847
<b>370-6</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540108	2460	6846
<b>380-2</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540164	2630	6863
<b>390-0</b>			
Blade .....	7540107		6830
Trans. ....	7540111	2450	6845
<b>390-8</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>390-063</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>395-4</b>			
Blade .....	7540167		6964
Trans. ....	7540164	2630	6863
<b>395-5</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>400-4; 400-5; 400-63; 400-063; 400-64; 400-65</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>410-0; 410-3; 410-9; 412-1; 412-2</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>420-9; 425-2; 425-3</b>			
Deck .....	7540127		6966
Drive .....	7540135		6925
Trans. ....	7540136		6931
<b>445-4</b>			
Blade .....	7540178	3820	6982
Drive .....	7540185		6849
<b>445-5</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540200		6848
<b>460-0; 460-8; 460-9</b>			
Blade .....	7540118		6963
Gen. ....	7540134	7330	
Trans. ....	7540937	3590	6959
<b>465-63; 465-063</b>			
Blade .....	7540151		6967
Deck .....	7540138	3500	6950
Trans. ....	7540136		6931
<b>480-1</b>			
Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
<b>480-3</b>			
Drive .....	7540127		6966

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SENTRY - Continued</b>			
<b>490-1</b>			
Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/52" Belt O.C. ....	7540147	3520	6952
<b>495-3</b>			
Deck .....	7540145		6488BR
Trans. ....	7540127		6966
Variable Speed .....	7540173	3370	6937
<b>495-4; 495-5</b>			
Blade .....	7540145		6488BR
Drive .....	7540173	3370	6937
<b>497-63; 497-063</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>796-63</b>			
Drive; W/42" Belt O.C. ....	7540207		6842
Drive; W/62" Belt O.C. ....	7540198		6451BR
<b>Peerless Transaxle</b>			
Belt; W/85" Belt O.C. ....	7540266		6775BR
<b>SETAG</b>			
<b>38-101; 41-001</b>			
Deck .....			6831
Drive .....			6378
<b>SHAW</b>			
<b>Bush Hog Tractor VE3-6; Bush Hog Tractor VE4-7; Bush Hog Tractor VR3-6; Bush Hog Tractor VR4-6; Bush Hog Tractor VR4-7</b>			
Gen.; W/Wisconsin S7D Eng. ....			6832
Gen.; W/Wisconsin TRA10D Eng. ....	S1669		6836
P.T.O. ....	S2952		3V250
<b>SIMPLICITY</b>			
<b>12.5LTG</b>			
Drive; Mfr. No. 1691891 .....	1703836		6524BR
<b>12.5LTH</b>			
Drive; Mfr. No. 1691795, 1691886 .....	1721532		6798BR
<b>12FCG</b>			
Drive; Mfr. No. 1691654 .....	1678354		6842
<b>12LTG</b>			
Drive; Mfr. No. 1691427 .....	1716854		6643BR
<b>12LTH</b>			
Drive; Mfr. No. 1691931 .....	1656960		6811BR
<b>12RTG</b>			
Drive; Mfr. No. 1692049 .....	1716854		6643BR
Drive; Mfr. No. 1692094 .....	1708114		6895
<b>12RTH</b>			
Drive; Mfr. No. 1692053 .....	1656960		6811BR
<b>14GTG</b>			
Drive; Mfr. No. 1692024 .....	1707381		6503BR
<b>16GTH</b>			
Drive; Mfr. No. 1691766 .....	1656960		6811BR
Drive; Mfr. No. 1692042 .....	170164		A75
<b>16LTH</b>			
Drive; Mfr. No. 1691807 .....	1721532		6798BR
<b>17GTH</b>			
Drive; Mfr. No. 1691824 .....	1656960		6811BR
<b>17GTH-L</b>			
Drive; Mfr. No. 1691957 .....	1650502		6422BR
<b>18GTH</b>			
P.T.O.; Sunstar Series; Mfr. No. 1691924 .....	1674726		②A34
<b>20GTH</b>			
P.T.O.; Sunstar Series; Mfr. No. 1691926 .....	1674726		②A34

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>				<b>SIMPLICITY - Continued</b>			
<b>705; 953; 954</b>				<b>990432; 990433 – Continued</b>			
Drive .....	170921		6824	Gen. ....	122146		6738
<b>3108</b>				<b>990434; 990435</b>			
Drive; Mfr. No. 1691551 .....	1665706		6839	Starter/Gen. ....	157524	7390	
<b>3110</b>				<b>990485</b>			
Drive; W/10 H.P. Eng.; Mfr. No. 1691535, 1691537 .....	1665706		6839	Drive .....	163011		6525BR
<b>4210G</b>				<b>990486</b>			
Drive; Mfr. No. 1691541 .....	1716854		6643BR	Drive .....	162081		6876
<b>4212G</b>				<b>990489</b>			
Drive; Mfr. No. 1691427 .....	1716854		6643BR	Drive .....	165048		6775BR
<b>4212H</b>				Gen. ....	122120		6734
Drive; Mfr. No. 1691340 .....	1670835		6458BR	<b>990494; 990495</b>			
<b>5212.5G</b>				P.T.O. ....			6834
Drive; Mfr. No. 1691431 .....	1703836		6524BR	Power Lift Attachment .....	157230		6722
<b>5212.5H</b>				Starter/Gen. ....	157524	7390	
Drive; Mfr. No. 1691473 .....	1672135		6523BR	<b>990496; 990497</b>			
<b>5216H</b>				Drive .....	154273		6942
Drive; Mfr. No. 1691362, 1691649 .....	1672135		6523BR	P.T.O. ....	154307		6835
<b>7117H</b>				Power Lift Attachment .....	157230		6722
Drive; Mfr. No. 1691717 .....	1650502		6422BR	Starter/Gen. ....	122146		6738
<b>169135</b>				<b>990499; 990500</b>			
Belt; W/42" Deck; W/16 H.P. Eng. ....	1668066		6481BR	Drive .....	166172		6847
<b>990086; 990120</b>				P.T.O. ....			6834
Drive .....	121078		6835	Power Lift Attachment .....	157230		6722
P.T.O. ....	118068		6834	Starter/Gen. ....	157524	7390	
<b>990154; 990165; 990230</b>				<b>990542</b>			
Drive .....	121228		6837	Drive .....	162081		6876
P.T.O. ....	121216		6838	<b>990554</b>			
<b>990234</b>				Drive .....	158573		A29
Drive .....	121078		6835	Mower .....	108248		6848
<b>990287; 990288; 990303</b>				<b>990568; 990569</b>			
Clutch .....	156231		6842	P.T.O. ....	157683		6829
Gen. ....	122120		6734	Power Lift Attachment .....	157230		6722
Trans. ....	156120		6863	Starter/Gen. ....	122146		6738
<b>990308; 990314</b>				<b>990570; 990571</b>			
Drive .....	154273		6942	P.T.O. ....	157683		6829
P.T.O. ....	106390		6836	Power Lift Attachment .....	157230		6722
Starter/Gen. ....	122146		6738	Starter/Gen. ....	157524	7390	
<b>990329; 990332</b>				<b>990572; 990573</b>			
Drive .....	108248		6848	Drive .....	166172		6847
P.T.O. ....	108099		6844	P.T.O. ....	157683		6829
<b>990357</b>				Power Lift Attachment .....	157230		6722
Drive .....	158460		6831	Starter/Gen. ....	157524	7390	
P.T.O. ....	158389		6829	<b>990577</b>			
<b>990373; 990374; 990375</b>				Drive .....	165048		6775BR
Clutch .....	156231		6842	Gen. ....	122120		6734
Gen. ....	122120		6734	<b>990578; 990579</b>			
Trans. ....	156120		6863	Drive .....	162081		6876
<b>990390</b>				<b>990580; 990581</b>			
Drive .....	158389		6829	Drive .....	163011		6525BR
P.T.O. ....	158389		6829	<b>990614</b>			
<b>990399; 990400</b>				Drive .....	158573		A29
Drive .....	154273		6942	Mower .....	170164		A75
Starter/Gen. ....	157524	7390		P.T.O. ....			6834
<b>990415</b>				<b>990645; 990646</b>			
Drive .....	162081		6876	Drive .....	162081		6876
<b>990418</b>				<b>990647; 990648</b>			
Drive .....	163011		6525BR	Drive .....	163011		6525BR
<b>990424; 990425</b>				<b>990653</b>			
Clutch .....	156231		6842	P.T.O. ....	157683		6829
Gen. ....	122120		6734	Starter/Gen. ....	122146		6738
Trans. ....	156120		6863	<b>990654</b>			
<b>990432; 990433</b>				P.T.O. ....	172066		6929
Drive .....	154273		6942	Starter/Gen. ....	157524	7390	
				<b>990655</b>			
				Drive .....	166172		6847



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>990655 – Continued</b>			
P.T.O. ....	172066		6929
Starter/Gen. ....	157524	7390	
<b>990657</b>			
Drive ....	166172		6847
P.T.O. ....	172066		6929
Starter/Gen. ....	122146		6738
<b>990755</b>			
Drive ....	174364		6849
Starter/Gen. ....	157524	7390	
<b>990756</b>			
Clutch ....	174883		6834
Drive ....			6853
Starter/Gen. ....	157524	7390	
<b>990757</b>			
Drive ....	166172		6847
Starter/Gen. ....	157524	7390	
<b>990758</b>			
Clutch ....	174883		6834
Drive ....			6853
Starter/Gen. ....	157524	7390	
<b>990759</b>			
Drive ....	166172		6847
Starter/Gen. ....	157524	7390	
<b>990763; 990764</b>			
Drive ....	162081		6876
<b>990765</b>			
Drive ....	165048		6775BR
Gen. ....	122120		6734
<b>990774; 990775</b>			
Drive ....	158573		A29
Mower ....	174911		6844
<b>990871</b>			
Drive ....	166172		6847
Starter/Gen. ....	157524		6739
<b>990872</b>			
Clutch ....	174883		6834
Drive ....			6853
Starter/Gen. ....	157524		6739
<b>990898</b>			
Drive ....	165048		6775BR
Gen. ....	122120		6734
<b>990899</b>			
Drive ....	162081		6876
<b>990900</b>			
Drive ....	158573		A29
Mower ....	174911		6844
<b>990979; 990980</b>			
Clutch; W/47" Belt O.C. ....	166172		6847
Clutch; W/53" Belt O.C. ....			6853
Forward ....	174883		6834
Starter/Gen. ....	157524	7390	
<b>991000</b>			
Drive ....	175361		6829
<b>991020</b>			
Drive ....	1608954	2330	6833
P.T.O. ....	1608960		6837
<b>1393764</b>			
P.T.O. ....	1716996		6836
<b>1690006</b>			
Drive ....	1650502		6422BR
Starter/Gen. ....	157524	7390	
<b>1690007; 1690008</b>			
Drive ....	165048		6775BR
<b>1690012</b>			
Drive ....	1651201		6873

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>1690012 – Continued</b>			
P.T.O. ....	176451		A133
<b>1690015</b>			
Clutch ....	174883		6834
Drive ....			6853
Starter/Gen. ....	157524	7390	
<b>1690016</b>			
Drive ....	174364		6849
Starter/Gen. ....	157424		6739
<b>1690072</b>			
Drive ....	170921		6824
<b>1690086</b>			
Drive ....	174364		6849
Starter/Gen. ....	157424		6739
<b>1690090; 1690118</b>			
Drive ....	165048		6775BR
<b>1690124</b>			
Drive ....	158573		A29
<b>1690128</b>			
Drive ....	1608954	2330	6833
Mower ....	1608957		6849
P.T.O. ....	1608960		6837
<b>1690192; 1690193</b>			
Trans. ....	165048		6775BR
<b>1690202</b>			
Drive ....	1650502		6422BR
Starter/Gen. ....	157524	7390	
<b>1690203; 1690204</b>			
Drive ....	1607967		6639BR
Starter/Gen. ....	157524	7390	
<b>1690206; 1690207; 1690208</b>			
Drive ....	1655069		6524BR
Mower ....	108505		6870
<b>1690230</b>			
Drive ....	170921		6824
<b>1690232</b>			
Clutch ....	174883		6834
Drive ....			6853
Starter/Gen. ....	157524	7390	
<b>1690240</b>			
Drive ....	158573		A29
<b>1690242</b>			
Drive ....	1608954	2330	6833
Mower ....	1608957		6849
P.T.O. ....	1608960		6837
<b>1690259; 1690261</b>			
Drive ....	1655069		6524BR
<b>1690283</b>			
Drive ....	170921		6824
<b>1690333</b>			
Drive ....	1607967		6639BR
<b>1690337</b>			
Clutch ....	174883		6834
Drive ....			6853
<b>1690341</b>			
Drive ....	1607967		6639BR
<b>1690342</b>			
Belt ....	1650502		6422BR
<b>1690343</b>			
Drive ....	1655069		6524BR
<b>1690347</b>			
Trans. ....	165048		6775BR
<b>1690423; 1690425</b>			
Drive ....	1607967		6639BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>1690427; 1690429; 1690431; 1690433</b>			
Belt .....	1650502		6422BR
<b>1690448; 1690450</b>			
Trans. ....	1665450		6627BR
<b>1690456; 1690458</b>			
Drive .....	1666698		6643BR
<b>1690472</b>			
Drive .....	1607967		6639BR
<b>1690473</b>			
Belt .....	1650502		6422BR
<b>1690474</b>			
Clutch .....	174883		6834
Drive .....			6853
<b>1690475; 1690476</b>			
Drive .....	1607967		6639BR
<b>1690480</b>			
Belt .....	1650502		6422BR
<b>1690525; 1690526; 1690527; 1690528</b>			
Drive .....	1665706		6839
<b>1690569; 1690570; 1690571</b>			
Belt .....	1650502		6422BR
<b>1690573</b>			
Primary .....	1669937		6954
<b>1690629</b>			
Drive .....	1655069		6524BR
<b>1690638; 1690640</b>			
Belt .....	1650502		6422BR
Drive .....	1607967		6639BR
<b>1690644; 1690646; 1690648</b>			
Drive .....	1607967		6639BR
<b>1690658; 1690660</b>			
Clutch .....	174883		6834
Drive .....			6853
<b>1690683</b>			
Primary .....	1669937		6954
<b>1690684</b>			
Drive .....	1655069		6524BR
<b>1690688; 1690695</b>			
Primary .....	1669937		6954
<b>1690721</b>			
Clutch .....	174883		6834
Drive .....			6853
<b>1690723</b>			
Belt .....	1650502		6422BR
<b>1690725; 1690740</b>			
Clutch .....	174883		6834
Drive .....			6853
<b>1690747</b>			
Belt .....	1650502		6422BR
<b>1690750</b>			
Clutch .....	174883		6834
Drive; W/52" Belt O.C. ....	1607967		6639BR
Drive; W/53" Belt O.C. ....			6853
<b>1690751</b>			
Belt .....	1650502		6422BR
<b>1690752</b>			
Clutch .....	174883		6834
Drive .....			6853
<b>1690756; 1690757</b>			
Primary .....	1669937		6954
<b>1690759</b>			
Drive .....	1670835		6458BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>1690786</b>			
Primary .....	1669937		6954
<b>1690810</b>			
Belt; W/42" Deck; W/16 H.P. Eng. ....	1668066		6481BR
Drive .....	1672135		6523BR
<b>1690840; 1690843</b>			
Drive .....	1666698		6643BR
<b>1690846</b>			
Drive .....	1670835		6458BR
<b>1690849</b>			
Drive .....	1655069		6524BR
<b>1690853; 1690881</b>			
Drive .....	1672135		6523BR
<b>1690909</b>			
Drive .....	1666698		6643BR
<b>1690915</b>			
Drive .....	1655069		6524BR
<b>1690919</b>			
Drive .....	1672135		6523BR
<b>1690927</b>			
Primary .....	1674898		6950
Secondary .....	1674899		6956
<b>1690934</b>			
Drive .....	1655069		6524BR
<b>1690936</b>			
Drive .....	1672135		6523BR
<b>1691027; 1691028</b>			
Drive .....	1666698		6643BR
<b>1691031</b>			
Drive .....	1655069		6524BR
<b>1691032; 1691033</b>			
Drive .....	1672135		6523BR
<b>1691034; 1691035</b>			
Primary .....	1674898		6950
Secondary .....	1674899		6956
<b>1691106; 1691108</b>			
Drive .....	1665706		6839
<b>1691175</b>			
Drive .....	1655069		6524BR
<b>1691198</b>			
Drive; W/12 H.P. Eng. ....	1678354		6842
<b>1691234; 1691235</b>			
Drive .....	1672135		6523BR
<b>1691238</b>			
Drive .....	1655069		6524BR
<b>1691240</b>			
Primary .....	1674898		6950
Secondary .....	1674899		6956
<b>1691250</b>			
P.T.O. ....	1674726		A34
<b>1691263 Hydro</b>			
Blower; W/42" Deck; W/16 H.P. Eng. ....	1700415		6732
Trans.; W/42" Deck; W/16 H.P. Eng. ....	1656960		6811BR
<b>1691269</b>			
Drive .....	1666698		6643BR
<b>1691330</b>			
Drive; W/8 H.P. Eng. ....	1678354		6842
<b>1691340</b>			
Drive .....	1670835		6458BR
<b>1691357</b>			
P.T.O. ....	1674726		A34



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>				<b>SIMPLICITY - Continued</b>			
1691362 Drive ..... 1672135			6523BR	1692042 Drive ..... 170164			A75
1691381 P.T.O. .... 1674726			A34	1692049 Drive ..... 1716854			6643BR
1691382 Trans. .... 1650502			6422BR	1692053 Drive ..... 1656960			6811BR
1691427 Drive ..... 1716854			6643BR	1692071; 1692073 Drive ..... 1713515			6458BR
1691431 Drive ..... 1703836			6524BR	1692094 Drive ..... 1708114			A93
1691473 Drive ..... 1672135			6523BR	1692129 Drive ..... 1676460			6843
1691528 P.T.O. .... 1674726			A34	1692131 P.T.O. .... 1708529			A35
1691535; 1691537 Drive ..... 1665706			6839	1692133; 1692135 P.T.O. .... 1708529			ⓂA35
1691541 Drive ..... 1716854			6643BR	1692143 Drive ..... 1650502			6422BR
1691551 Drive ..... 1665706			6839	1692156 Drive ..... 1656960			6811BR
1691654 Drive ..... 1678354			6842	1692160 Drive ..... 1708114			A93
1691686 Deck ..... 1668066			6481BR	1692168 Drive ..... 1676460			6843
1691687 Deck; W/16 H.P. Eng. .... 1665638			6560	1692182 Drive ..... 1713515			6458BR
1691710 P.T.O. .... 1674726			A34	1692259 Drive ..... 170164			A75
1691717 Trans. .... 1650502			6422BR	1692261; 1692279; 1692283 Drive ..... 1672135			6523BR
1691766 Drive ..... 1656960			6811BR	1692287 Drive ..... 1657044			6521BR
1691795; 1691807 Drive ..... 1721532			6798BR	1692301 Drive ..... 1707381			6503BR
1691824 Drive ..... 1656960			6811BR	1692354 Drive ..... 1672135			6523BR
1691841; 1691842 Drive ..... 1707345 P.T.O. .... 1705107			6844 6939	1692380; 1692382 Drive ..... 1676460			6843
1691843; 1691844; 1691845; 1691846 Drive ..... 1707344 P.T.O. .... 1705106			6841 6937	1692401 Drive ..... 1708114			A93
1691886 Drive ..... 1721532			6798BR	1692403 Drive ..... 170164			A75
1691891 Drive ..... 1703836			6524BR	1692414; 1692416 Drive ..... 1672135			6523BR
1691924; 1691926 P.T.O. .... 1674726			A34	1692418 Drive ..... 1657044			6521BR
1691931 Drive ..... 1656960			6811BR	1692420 Drive ..... 1672135			6523BR
1691957 Drive ..... 1650502			6422BR	1692438 Drive ..... 1707381			6503BR
1691964; 1691965 Drive ..... 1707347 P.T.O. .... 1705107			6845 6939	1692440; 1692442 Drive ..... 170164			A75
1691966; 1691967; 1691968; 1691969 Drive ..... 1707346 P.T.O. .... 1705106			6842 6937	1692450 Drive ..... 1650502			6422BR
1692006 Drive ..... 170164			A75	1692454; 1692456; 1692521 P.T.O. .... 1708529			ⓂA35
1692024 Drive ..... 1707381			6503BR	1692528 Drive ..... 1672135			6523BR
				1692576 Drive ..... 1707381			6503BR

ⓂTwo Required

RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
1692593 Drive .....	1657044		6521BR
1692609 Drive .....	1672135		6523BR
1692631 Drive .....	170164		A75
1692748 Drive .....	1676460		6843
1692760 Drive .....	1657044		6521BR
1692762 Drive .....	1719819		6434BR
1692772; 1692774; 1692776 Drive .....	1672135		6523BR
1692784; 1692786; 1692788 Drive .....	1707381		6503BR
1692796; 1692798 Drive .....	1650502		6422BR
1692870 P.T.O. ....	1716996		6836
1692871 P.T.O. ....	1716995		6836
1692872 P.T.O. ....	1716996		6836
1692873 Drive .....	1672135		6523BR
1692889 Drive .....	1650502		6422BR
1692905; 1692906 Drive .....	1705142		6738
1692943; 1692945 Drive .....	1650502		6422BR
1692957; 1692959; 1692961; 1692963; 1692965; 1692967; 1692969; 1692971; 1692973; 1692975 Drive .....	1672135		6523BR
1693008; 1693012; 1693016 Drive .....	1707381		6503BR
1693030 Drive .....	1676460		6843
1693052; 1693054; 1693056 Drive .....	1717932		6811BR
1693074 Drive .....	1657044		6521BR
1693080 Drive .....	1717397		6798BR
1693084 Drive .....	1657044		6521BR
1693088 Drive .....	1717397		6798BR
1693112 P.T.O. ....	1718602		6834
1693219 P.T.O. ....	1716996		6836
1693230 Drive .....	1719381		6838
1693275 Drive .....	1717932		6811BR
1693286; 1693288 Drive .....	1705142		6738
1693303 Drive .....	1676460		6843

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
1693323 Drive .....	1657044		6521BR
1693325; 1693329 Drive .....	1717397		6798BR
1693351; 1693353; 1693355 Drive .....	1717932		6811BR
1693379; 1693381; 1693383 Drive .....	1719398		6714BR
1693407; 1693409 Drive .....	1650502		6422BR
1693452 Drive .....	1665450		6627BR
1693458 Drive .....	1717397		6798BR
1693467; 1693473 Drive .....	1719381		6838
1693525; 1693528; 1693530; 1693532 Drive .....	1717397		6798BR
1693561 P.T.O. ....	1716996		6836
1693580; 1693592; 1693600 Drive .....	1717932		6811BR
1693694 Drive .....	1719819		6434BR
1693804; 1693806 Drive .....	1719398		6714BR
1693839 Drive .....	1719819		6434BR
<b>Axion</b> Blade Drive; W/50" Deck .....	1732204		6524BR
Deck Drive; W/33" Deck .....	7102246		6675BR
Deck Drive; W/42" Deck .....	1732966		6765BR
Trans. ....	1732224		6697BR
<b>Badgers Regent</b> Drive; Mfr. No. 1692967 .....	1672135		6523BR
<b>Broadmoor</b> Arbor; W/44" Deck .....	1721532		6798BR
Arbor; W/46" Deck .....	1666801		6640BR
Arbor; W/50" Deck .....	1703836		6524BR
Arbor; W/52" Deck .....	1665450		6627BR
Drive; W/12.5 H.P. Eng.; Gear Model; Mfr. No. 1691891 .....	1703836		6524BR
Drive; W/12.5 H.P. Eng.; Hydro. Model; Mfr. No. 1692073 .....	1713515		6458BR
Drive; W/12.5 H.P. Eng.; Hydro. Model; Mfr. No. 1692261 .....	1672135		6523BR
Drive; W/14 H.P. Eng.; Hydro. Model; Mfr. No. 1692182 .....	1713515		6458BR
Drive; W/14 H.P. Eng.; Hydro. Model; Mfr. No. 1692279, 1692414, 1692416, 1692772 .....	1672135		6523BR
Drive; W/14 H.P. Eng.; Hydro. Model; Mfr. No. 1693052, 1693351 .....	1717932		6811BR
Drive; W/15 H.P. Eng.; Gear Model; Mfr. No. 1692287, 1692418 .....	1657044		6521BR
Drive; W/15 H.P. Eng.; Hydro. Model; Mfr. No. 1692528, 1692609, 1692774 .....	1672135		6523BR
Drive; W/15 H.P. Eng.; Hydro. Model; Mfr. No. 1693054, 1693353 .....	1717932		6811BR
Drive; W/16 H.P. Eng.; Hydro. Model; Mfr. No. 1692071 .....	1713515		6458BR
Drive; W/16 H.P. Eng.; Hydro. Model; Mfr. No. 1692283, 1692420, 1692776 .....	1672135		6523BR
Drive; W/16 H.P. Eng.; Hydro. Model; Mfr. No. 1693056, 1693355, 1693580, 1693592 .....	1717932		6811BR
Drive; W/16 H.P. Eng.; Hydro. Model; Mfr. No. 1693839 .....	1719819		6434BR
Drive; W/17 H.P. Eng.; Hydro. Model; Mfr. No. 1693694 .....	1719819		6434BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>Broadmoor – Continued</b>			
Drive; W/18 H.P. Eng.; Hydro. Model; Mfr. No. 1693275, 1693600 .....	1717932		6811BR
P.T.O.; W/44" Deck .....	1601672		6799BR
P.T.O.; W/50" Deck .....	1707740		6869
P.T.O.; W/52" Deck .....	2101137		A66
Trans. ....	1726841		6710BR
<b>CFC</b>			
Drive; W/16 H.P. Eng.; Mfr. No. 1691841, 1691842 .....	1707345		6844
Drive; W/16 H.P. Eng.; Mfr. No. 1691964, 1691965 .....	1707347		6845
Drive; W/18 H.P. Eng.; Mfr. No. 1691843, 1691844 .....	1707344		6841
Drive; W/18 H.P. Eng.; Mfr. No. 1691966, 1691967 .....	1707346		6842
Drive; W/20 H.P. Eng.; Mfr. No. 1691845, 1691846 .....	1707344		6841
Drive; W/20 H.P. Eng.; Mfr. No. 1691968, 1691969 .....	1707346		6842
P.T.O.; W/16 H.P. Eng.; Mfr. No. 1691841, 1691842 .....	1705107		6939
P.T.O.; W/18 H.P. Eng.; Mfr. No. 1691843, 1691844 .....	1705106		6937
P.T.O.; W/20 H.P. Eng.; Mfr. No. 1691845, 1691846 .....	1705106		6937
<b>Champion</b>			
Deck Drive; W/44" Deck .....	5023256		7017BR
Deck Drive; W/50" Deck .....	5023255		6876BR
Deck Drive; W/52" Deck .....	5023255		6876BR
<b>Chiefs Regent</b>			
Drive; Mfr. No. 1692963 .....	1672135		6523BR
<b>Citation</b>			
Deck Drive; W/48" Deck .....	5023297		6767BR
Deck Drive; W/52" Deck .....	5023435		6768BR
Deck Drive; W/61" Deck .....	5022061		6661BR
Hydro. Drive .....	5100555		6772BR
<b>Cobalt</b>			
Deck Drive; W/61" Deck .....	5022061		6661BR
Hydro. Drive .....	5100555		6772BR
<b>Colts Regent</b>			
Drive; Mfr. No. 1692965 .....	1672135		6523BR
<b>Conquest</b>			
Arbor; W/44" Deck .....	1601672		6799BR
Arbor; W/46" Deck .....	1666801		6640BR
Arbor; W/50" Deck .....	1703836		6524BR
Arbor; W/52" Deck .....	1665450		6627BR
Eng. To P.T.O.; W/44" Deck .....	1721532		6798BR
Eng. To P.T.O.; W/50" Deck .....	1707740		6869
Eng. To P.T.O.; W/52" Deck .....	2101137		A66
Trans. ....	1721392		6710BR
<b>Coronet</b>			
Deck Drive; W/34" Discharge 800 .....	1723391		6434BR
Deck P.T.O.; W/11 H.P. Eng. ....	1651201		6873
Drive; W/10.5 H.P. Eng.; Gear Model; Mfr. No. 1692748 .....	1676460		6843
Drive; W/11 H.P. Eng.; Gear Model; Mfr. No. 1693030, 1693303 .....	1676460		6843
Drive; W/12.5 H.P. Eng.; Gear Model; Mfr. No. 1692129, 1692382 .....	1676460		6843
Drive; W/8.5 H.P. Eng.; Gear Model; Mfr. No. 1692168, 1692380 .....	1676460		6843
Trans. ....	1707346		6842
<b>Express</b>			
Drive; W/14.5 H.P. Eng.; Gear Model; Mfr. No. 1693452 .....	1665450		6627BR
Drive; W/15 H.P. Eng.; Hydro. Model; Mfr. No. 1693458 .....	1717397		6798BR
Drive; W/17 H.P. Eng.; Hydro. Model; Mfr. No. 1693525 .....	1717397		6798BR
<b>Hawkeyes Regent</b>			
Drive; Mfr. No. 1692969 .....	1672135		6523BR
<b>Javelin</b>			
Deck Drive; W/38" Deck .....	1718017		6684BR

©Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>Javelin – Continued</b>			
Deck Drive; W/44" Deck .....	7100425		6779BR
Deck Drive; W/50" Deck .....	7100515		6745BR
Hydro. Drive .....	7100102		6871BR
<b>Landlord</b>			
Blade; W/17, 18 H.P. Eng.; W/50" Deck .	1703836		6524BR
Drive; W/16 H.P. Eng.; Gear Model; Mfr. No. 1692438 .....	1707381		6503BR
Drive; W/16 H.P. Eng.; Hydro. Model; Mfr. No. 1692301, 1692784, 1693008 ....	1707381		6503BR
Drive; W/16 H.P. Eng.; Hydro. Model; Mfr. No. 1692440, 1692631 .....	170164		A75
Drive; W/17 H.P. Eng.; Hydro. Model; Mfr. No. 1692786, 1693012 .....	1707381		6503BR
Drive; W/17 H.P. Eng.; Hydro. Model; Mfr. No. 1693379 .....	1719398		6714BR
Drive; W/18 H.P. Eng.; Hydro. Model; Mfr. No. 1692006, 1692442 .....	170164		A75
Drive; W/18 H.P. Eng.; Hydro. Model; Mfr. No. 1692576, 1692788, 1693016 ....	1707381		6503BR
Drive; W/18 H.P. Eng.; Hydro. Model; Mfr. No. 1693381, 1693806 .....	1719398		6714BR
Drive; W/20 H.P. Eng.; Hydro. Model; W/P.S.; Mfr. No. 1693383 .....	1719398		6714BR
Drive; W/23 H.P. Eng.; Hydro. Model; W/P.S.; Mfr. No. 1693804 .....	1719398		6714BR
P.T.O.; W/17, 18 H.P. Eng.; W/50" Deck .....	1707740		6869
<b>Legacy</b>			
P.T.O.; W/20 H.P. Eng.; Hydro. Model; W/23" Wheels; Mfr. No. 1692870 .....	1716996		6836
P.T.O.; W/20 H.P. Eng.; Hydro. Model; W/26" Wheels; Mfr. No. 1693219 .....	1716996		6836
P.T.O.; W/20 H.P. LC Eng.; Hydro. Model; Mfr. No. 1692871 .....	1716995		6836
P.T.O.; W/23 H.P. Eng.; Mfr. No. 1693764 .....	1716996		6836
P.T.O.; W/24.5 H.P. Eng.; Hydro. Model; Mfr. No. 1693112 .....	1718602		6834
P.T.O.; W/25 H.P. Eng.; Hydro. Model; Mfr. No. 1692872, 1693561 .....	1716996		6836
<b>Legacy XL</b>			
Arbor; W/48" Deck .....	174911		6844
Eng. To P.T.O.; W/48" Deck .....	1725557		6860
Eng. To P.T.O.; W/60" Deck .....	1725154		6756BR
<b>LPH</b>			
Belt; W/38" Deck; W/16 H.P. Eng. ....	1601672		6799BR
<b>LTH Group</b>			
Belt; W/12.5 H.P. Eng.; Mfr. No. 1691745, 1691886 .....	1650502		6422BR
<b>Nittany Lions Regent</b>			
Drive; Mfr. No. 1692975 .....	1672135		6523BR
<b>Packer Backer Regent</b>			
Drive; Mfr. No. 1692873 .....	1672135		6523BR
<b>Panthers Regent</b>			
Drive; Mfr. No. 1692961 .....	1672135		6523BR
<b>Prestige</b>			
Arbor; W/44" Deck .....	1601672		6799BR
Arbor; W/50" Deck .....	1703836		6524BR
Arbor; W/54" Deck .....	1671076		6765BR
Eng. To P.T.O.; W/44" Deck .....	1721532		6798BR
Eng. To P.T.O.; W/50" Deck .....	1707740		6869
Eng. To P.T.O.; W/54" Deck .....	1722039		6525BR
Trans. ....	1721393		6710BR
<b>Regent</b>			
Deck Drive; W/38" Deck; W/Narrow Pulley .....	1723025		6714BR
Deck Drive; W/44" Deck .....	1729627		6848BR
Deck Drive; W/46" Deck .....	1732956		6715BR
Deck Drive; W/50" Deck; W/Narrow Pulley .....	1703466		6484BR
Drive; W/12.5 H.P. Eng.; Gear Model; Mfr. No. 1692160, 1692401 .....	1708114		6895
Drive; W/12.5 H.P. Eng.; Hydro. Model; Mfr. No. 1692156 .....	1656960		6811BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>Regent - Continued</b>			
Drive; W/12.5 H.P. Eng.; Hydro. Model; Mfr. No. 1692259, 1692403 .....	170164		A75
Drive; W/14 H.P. Eng.; Gear Model; Mfr. No. 1692593, 1693074, 1693323 .....	1657044		6521BR
Drive; W/14 H.P. Eng.; Hydro. Model; Mfr. No. 1692354 .....	1672135		6523BR
Drive; W/14 H.P. Eng.; Hydro. Model; Mfr. No. 1693080, 1693325 .....	1717397		6798BR
Drive; W/15 H.P. Eng.; Hydro. Model; Mfr. No. 1693528 .....	1717397		6798BR
Drive; W/15.5 H.P. Eng.; Gear Model; Mfr. No. 1692760 .....	1657044		6521BR
Drive; W/16 H.P. Eng.; Gear Model; Mfr. No. 1693084 .....	1657044		6521BR
Drive; W/16 H.P. Eng.; Hydro. Model; Mfr. No. 1692762 .....	1719819		6434BR
Drive; W/16 H.P. Eng.; Hydro. Model; Mfr. No. 1693088, 1693329, 1693530 .....	1717397		6798BR
Drive; W/17 H.P. Eng.; Hydro. Model; Mfr. No. 1693532 .....	1717397		6798BR
P.T.O.; W/40" Deck; W/Large Pulley .....	1732955		6710BR
P.T.O.; W/40" Deck; W/Narrow Pulley .....	1721532		6798BR
Trans. ....	1728008		6709BR
<b>Regent 16 Speed</b>			
Drive .....	1672135		6523BR
<b>Sovereign</b>			
Drive; W/18 H.P. Eng.; Hydro. Model; Mfr. No. 1692796, 1692945 .....	1650502		6422BR
Drive; W/18 H.P. Eng.; Hydro. Model; W/P.S.; Mfr. No. 1692798, 1692943 .....	1650502		6422BR
Drive; W/18 H.P. Eng.; Mfr. No. 1692143, 1692450 .....	1650502		6422BR
P.T.O.; W/18 H.P. Eng.; Hydro. Model ...	1713515		6458BR
<b>Sovereign - 75Th Anniversary</b>			
Drive; W/18 H.P. Eng.; Mfr. No. 1692889 .....	1650502		6422BR
<b>Spartans Regent</b>			
Drive; Mfr. No. 1692973 .....	1672135		6523BR
<b>Steelers Regent</b>			
Drive; Mfr. No. 1692959 .....	1672135		6523BR
<b>Sunstar</b>			
P.T.O.; W/14 H.P. Eng.; Mfr. No. 1691250 .....	1674726		②A34
P.T.O.; W/16 H.P. Eng.; Mfr. No. 1691357 .....	1674726		②A34
P.T.O.; W/18 H.P. 18GTH Eng.; W/P.S.; Mfr. No. 1691528 .....	1674726		②A34
P.T.O.; W/20 H.P. 20GTH Eng.; Mfr. No. 1691381 .....	1674726		②A34
P.T.O.; W/20 H.P. Eng.; W/Lift & P.T.O.; Mfr. No. 1691710 .....	1674726		②A34
<b>Vikings Regent</b>			
Drive; Mfr. No. 1692957 .....	1672135		6523BR
<b>Wolverines Regent</b>			
Drive; Mfr. No. 1692971 .....	1672135		6523BR
<b>ZT</b>			
Drive; W/14 H.P. Eng.; Mfr. No. 1693467 .....	1719381		6838
Drive; W/16 H.P. Eng.; Mfr. No. 1693473 .....	1719381		6838
Drive; W/18 H.P. Eng.; Mfr. No. 1693230 .....	1719381		6838
<b>ZT3000</b>			
Deck Drive; W/44" Deck .....	5023256		7017BR
Deck Drive; W/46" Deck .....	5102145		6708BR
Deck Drive; W/50" Deck .....	5023255		6876BR
<b>ZT4000</b>			
Deck Drive; W/44" Deck .....	5023496		6599BR
Deck Drive; W/48" Deck .....	5023297		6767BR
Hydro. Drive .....	5100923		6482BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SMITH CO.</b>			
<b>Red Rider 9226-0040</b>			
Belt .....		2240	
<b>SNAPPER</b>			
<b>264R; 264X</b>			
Blade .....	10749		6455BR
<b>265X; 265XS; 266R; 266X; 266XS; 267X; 267XS; 268X; 268XS</b>			
Drive .....	10749		6455BR
<b>304R; 304RD; 305X; 305XS; 306R; 306RA; 306RD; 306RDS; 306W; 306X</b>			
Blade .....	10749		6455BR
<b>306XS; 307X; 307XS</b>			
Blade .....	10749		6455BR
<b>308X; 308XS</b>			
Drive .....	10749		6455BR
<b>311X5S</b>			
Blade; W/28", 30" Deck .....	10749		6455BR
Blade; W/33" Deck .....	18236		6471BR
Blade; W/41" Deck; W/2-Blades .....	14525		6456BR
<b>417X; 417XS; 418R; 418RS; 418X; 418XS</b>			
Drive .....	10749		6455BR
<b>1600 Series</b>			
Rear P.T.O. ....	19607		A37
Transaxle .....	19534		6835
<b>1650 Series</b>			
Rear P.T.O. ....	19607		A37
<b>1855 Series</b>			
Clutch & Mid P.T.O. ....	19551		A42
Rear P.T.O. ....	19607		A37
<b>2550; 2550S; 2610W; 2610WS</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>2650; 2650S</b>			
Drive .....	10749		6455BR
<b>2651; 2651S; 2652; 2652S; 2661S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>2680; 2680S</b>			
Drive .....	10749		6455BR
<b>2681; 2681S; 2681W; 2681WS</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>2808TE</b>			
Drive .....	18236		6471BR
<b>2810W; 2810WS</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>2811X5S; 2811X6S</b>			
Drive; W/28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>2812X6S</b>			
Drive; W/28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	22252		6471BR
Drive; W/41" Deck .....	24497		6456BR
<b>2880; 2880S; 2880W; 2880WS; 3010; 3010S; 3010W</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>3010WS</b>			
Blade; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>3011X5S</b>			
Drive; W/28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>3011X5S – Continued</b>			
Drive; W/41" Deck .....	14525		6456BR
<b>3011X6S; 3012X6S</b>			
Drive; W/28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	22252		6471BR
Drive; W/41" Deck .....	24497		6456BR
<b>3080; 3080S</b>			
Drive .....	10749		6455BR
<b>3081; 3081S; 3081W</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>3081WS</b>			
Drive .....	10749		6455BR
<b>3311</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>3311X5S</b>			
Drive; W/28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>3311X6S; 3312X6S</b>			
Drive; W/28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	22252		6471BR
Drive; W/41" Deck .....	24497		6456BR
<b>4111X5S</b>			
Drive; W/28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>4111X6S; 4112X6S</b>			
Drive; W/28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	22252		6471BR
Drive; W/41" Deck .....	24497		6456BR
<b>25062; 25062S; 25063; 25063S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>25064; 25064S; 25065; 25065S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>25066; 25066S</b>			
Drive .....	10749		6455BR
<b>25069T</b>			
Drive .....	18236		6471BR
<b>25083; 25083S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>25084; 25084BS; 25084S; 25085; 25085S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>25086</b>			
Drive .....	10749		6455BR
<b>25657B; 25657BE; 25659BE</b>			
Drive .....	18236		6471BR
<b>26062; 26062S; 26063; 26063S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>26064; 26064S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>26069T</b>			
Drive .....	18236		6471BR
<b>26083; 26083S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>26084; 26084B; 26084D</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>26084S</b>			
Drive .....	10749		6455BR
<b>26085; 26085BS; 26085S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>26086; 26086S</b>			
Drive .....	10749		6455BR
<b>26657; 26657BE; 26659BE</b>			
Drive .....	18236		6471BR
<b>28083; 28083S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>28084; 28084S; 28085; 28085S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>28086; 28086S</b>			
Drive .....	10749		6455BR
<b>28087B; 28087BE; 28088B; 28088BE; 28088T; 28088TE</b>			
Drive .....	18236		6471BR
<b>28106S</b>			
Drive .....	10749		6455BR
<b>28108E</b>			
Drive .....	18236		6471BR
<b>28113S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>28114S; 28115S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>28127BE; 28128BE; 28128TVE</b>			
Drive .....	18236		6471BR
<b>30083; 30083S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>30084; 30084S; 30085; 30085S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>30086; 30086S</b>			
Drive .....	10749		6455BR
<b>30087; 30087BE; 30088B; 30088BE; 30088T; 30088TE</b>			
Drive .....	18236		6471BR
<b>30106S</b>			
Drive .....	10749		6455BR
<b>30108BE</b>			
Drive .....	18236		6471BR
<b>30113S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>30114S; 30115S</b>			
Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>30116S</b>			
Blade; W/28", 30" Deck .....	10749		6455BR
Blade; W/33" Deck .....	18236		6471BR
Blade; W/41" Deck; W/2-Blades .....	14525		6456BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>30125BV</b> Deck; W/30" Deck .....	22252		6471BR
<b>30127BE; 30128BE; 30128RE; 30148KVE</b> Drive .....	18236		6471BR
<b>33113S</b> Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
<b>33114S; 33115S</b> Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>33115SC</b> Drive; W/28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>33127BE; 33128BE; 33128RE; 33128TVE; 33147BVE; 33147KE; 33148KVE</b> Drive .....	18236		6471BR
<b>41085; 41085S</b> Drive; W/25", 26", 28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>41115S</b> Blade; W/28", 30" Deck .....	10749		6455BR
Blade; W/33" Deck .....	18236		6471BR
Blade; W/41" Deck; W/2-Blades .....	14525		6456BR
<b>41115SC</b> Drive; W/28", 30" Deck .....	10749		6455BR
Drive; W/33" Deck .....	18236		6471BR
Drive; W/41" Deck .....	14525		6456BR
<b>41116S</b> Blade; W/28", 30" Deck .....	10749		6455BR
Blade; W/33" Deck .....	18236		6471BR
Blade; W/41" Deck; W/2-Blades .....	14525		6456BR
<b>41128BE</b> Drive .....	18236		6471BR
<b>42113S</b> Blade .....	12524		6990
<b>83304 Hydrostat</b> Belt; W/33" Deck .....	14799		6378
Belt; W/48" Deck; W/108" Belt O.C. ....	14525		6456BR
Belt; W/48" Deck; W/94" Belt O.C. ....	14801		6710BR
<b>250610T; 250612T</b> Drive .....	22252		6471BR
<b>250811BE</b> Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>250812BE</b> Drive .....	22252		6471BR
<b>250813BE</b> Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>250814B; 250814BE; 250815B; 250815BE; 250816B; 250816BE; 260610T; 260612T; 260810BE; 260810T</b> Drive .....	22252		6471BR
<b>280812BE</b> Drive .....	22252		6471BR
<b>280813BE</b> Deck .....	24497		6456BR
Drive .....	22252		6471BR
<b>280914BE</b> Drive .....	22252		6471BR
<b>280915BE</b> Drive .....	28619		6975

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>281011BE</b> Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>281013BE</b> Deck .....	24497		6456BR
Drive .....	22252		6471BR
<b>281014BE</b> Drive .....	22252		6471BR
<b>281016BE</b> Drive; Early .....	44637		6975
Drive; Late .....	43844		6635BR
<b>281123BV; 281123HVE; 281318BE; 281323BVE</b> Drive .....	43844		6635BR
<b>300810BE; 300810T; 300812B; 300812BE</b> Drive .....	22252		6471BR
<b>300813BE</b> Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>300914BE</b> Drive .....	22252		6471BR
<b>300915BE</b> Drive .....	28619		6975
<b>301011BE; 301013BE</b> Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>301014BE</b> Drive .....	22252		6471BR
<b>301016BE</b> Drive; Early .....	44637		6975
Drive; Late .....	43844		6635BR
<b>301123BVE; 301123HVE</b> Drive .....	43844		6635BR
<b>301213BE</b> Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>301214BE</b> Drive .....	22252		6471BR
<b>301215BE</b> Drive .....	28619		6975
<b>301216BE</b> Drive; Early .....	44637		6975
Drive; Late .....	43844		6635BR
<b>301318BE; 301323BVE</b> Drive .....	43844		6635BR
<b>301411KVE; 301413KVE; 331313BE</b> Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>331314BE</b> Drive .....	22252		6471BR
<b>331323HVE</b> Drive .....	43844		6635BR
<b>331411KVE; 331413KVE</b> Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>331414BE; 331414KVE</b> Drive .....	22252		6471BR
<b>331415BVE; 331415KVE</b> Drive .....	28619		6975
<b>331416BVE; 331416KVE</b> Drive; Early .....	44637		6975
Drive; Late .....	43844		6635BR
<b>331518KVE; 331523BVE; 331523KVE</b> Drive .....	43844		6635BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>381450HBVE; 381451HBVE</b>			
Deck .....	58231		6857
Eng. To Deck .....	71991		6860
Eng. To Hydro. ....	47117		6829
<b>411611BVE; 421613BVE</b>			
Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>421613BVE1; 421614BVE; 421614TVE</b>			
Deck .....	24497		6456BR
<b>2690249</b>			
Trans. ....	1707346		6842
<b>2690647</b>			
Deck; W/50" Deck .....	5023255		6876BR
Hydro. ....	5101033		6637BR
<b>2690801</b>			
Trans. ....	1707346		6842
<b>2690808</b>			
Deck Drive .....	1732955		6710BR
Trans. ....	1728008		6709BR
<b>2690809</b>			
Deck Drive .....	1732956		6715BR
Trans. ....	1728008		6709BR
<b>2690846</b>			
Deck Drive .....	1732955		6710BR
Trans. ....	1728008		6709BR
<b>2690847</b>			
Deck Drive .....	1732956		6715BR
Trans. ....	1728008		6709BR
<b>2690848</b>			
Deck Drive .....	1736516		6727BR
Trans. ....	1728008		6709BR
<b>2690858</b>			
Primary .....	1727869		6798BR
Secondary .....	720404		6475BR
Trans. ....	7101794		6474BR
<b>2810523BVE</b>			
Drive .....	43844		6635BR
<b>2811511BE</b>			
Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>3010523BV</b>			
Drive .....	43844		6635BR
<b>3011511BE; 3312511BE; 3312513BE</b>			
Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>3314518BVE</b>			
Drive .....	43844		6635BR
<b>5900681</b>			
Deck; W/44" Deck .....	5023256		7017BR
Hydro. ....	5101033		6637BR
<b>5900682; 5900685</b>			
Deck Drive .....	5023255		6876BR
Hydro. ....	5101033		6637BR
<b>5900706</b>			
Deck; W/50" Deck .....	5023255		6876BR
<b>5900731</b>			
Deck; W/48" Deck .....	5101301		6567BR
Hydro. ....	5022173		6743BR
<b>5900760</b>			
Deck Drive .....	5023255		6876BR
Hydro. ....	5101033		6637BR
<b>5900768</b>			
Hydro. ....	5101033		6637BR
<b>5900775</b>			
Deck Drive .....	5102145		6708BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>5900775 - Continued</b>			
Hydro. ....	5101033		6637BR
<b>5900946</b>			
Deck Drive .....	5023255		6876BR
Hydro. ....	5101033		6637BR
<b>5900982</b>			
Deck Drive .....	5101301		6567BR
Hydro. ....	5022173		6743BR
<b>7084940; 7085622</b>			
Deck Drive .....	7022252		6471BR
<b>7800009</b>			
Deck; W/38" Deck .....	7100691		6684BR
Hydro. ....	7100102		6871BR
<b>7800010</b>			
Deck; W/42" Deck .....	7100419		6874BR
Hydro. ....	7100102		6871BR
<b>7800011</b>			
Deck; W/50" Deck .....	7100515		6745BR
Hydro. ....	7100102		6871BR
<b>7800102</b>			
Deck; W/28" Deck .....	22252		6471BR
<b>7800103</b>			
Deck; W/30" Deck .....	22252		6471BR
<b>7800104</b>			
Deck; W/28" Deck .....	22252		6471BR
<b>7800107</b>			
Deck; W/33" Deck .....	43844		6635BR
<b>7800254</b>			
Deck Drive .....	7043844		6635BR
<b>7800269</b>			
Deck Drive .....	7102246		6675BR
Hydro. ....	1732224		6697BR
<b>7800386</b>			
Deck Drive .....	1732966		6765BR
Hydro. ....	1732224		6697BR
<b>7800387</b>			
Blade Drive .....	1732204		6524BR
Hydro. ....	1732224		6697BR
<b>7800392</b>			
Deck Drive .....	7102246		6675BR
Hydro. ....	1732224		6697BR
<b>7800393</b>			
Deck Drive .....	1732966		6765BR
Hydro. ....	1732224		6697BR
<b>7800394</b>			
Blade Drive .....	1732204		6524BR
Hydro. ....	1732224		6697BR
<b>7800478; 7800542; 7800545; 7800545E;</b>			
<b>7800546</b>			
Primary .....	1727869		6798BR
Secondary .....	720404		6475BR
Trans. ....	7101794		6474BR
<b>7800620</b>			
Deck Drive .....	7102246		6675BR
Hydro. ....	1732224		6697BR
<b>7800621</b>			
Deck Drive .....	1732966		6765BR
Hydro. ....	1732224		6697BR
<b>7800647; 7800649</b>			
Deck Drive .....	7022252		6471BR
<b>7800652</b>			
Deck Drive .....	7043844		6635BR
<b>BH120G38AB</b>			
Deck .....	24614		6898
Traction .....	24039		6897

Lawn & Garden Equipment





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>BH140G42AB</b>			
Deck; 1993 .....	14799		6378
Traction; 1993 .....	29641		6765BR
Traction; 1994 .....	25042		6898
<b>BH140H33BBV</b>			
Deck .....	26546		6856
Traction .....	28585		6896
<b>BH140H38BBV</b>			
Deck .....	29641		6765BR
Traction .....	28334		6894
<b>CZT19480KWV</b>			
Deck Drive .....	7011219		6745BR
Hydro. Drive .....	7075109		7026BR
<b>CZT19481KWV</b>			
Deck Drive .....	7011219		6745BR
<b>E250811B; E250811BE; E250813B; E250813BE</b>			
Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>E250814BE; E250815BE; E250816BE</b>			
Drive .....	22252		6471BR
<b>E250818BE</b>			
Drive .....	10749		6455BR
<b>E280813BE</b>			
Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>E280915BE</b>			
Drive .....	28619		6975
<b>E281011BE</b>			
Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>E281014BE</b>			
Drive .....	22252		6471BR
<b>E281016BE</b>			
Drive .....	43844		6635BR
<b>E281018BE</b>			
Drive .....	10749		6455BR
<b>E281022BE</b>			
Drive .....	43844		6635BR
<b>E281213BE</b>			
Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>E281216BE; E281222BE; E281318BE</b>			
Drive .....	43844		6635BR
<b>E331313BE</b>			
Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>E331314BE</b>			
Drive .....	22252		6471BR
<b>E331315BVE</b>			
Drive .....	28619		6975
<b>E331316BVE</b>			
Drive .....	43844		6635BR
<b>E331411KVE; E331413KVE</b>			
Deck .....	14525		6456BR
Drive .....	22252		6471BR
<b>E331414KVE</b>			
Drive .....	22252		6471BR
<b>E331415KVE</b>			
Drive .....	28619		6975
<b>E331416KVE; E331518KVE; E331522KVE</b>			
Drive .....	43844		6635BR
<b>E421613BV; E2811511BE; E3312511BE; E3312513BE</b>			
Deck .....	14525		6456BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>E421613BV; E2811511BE; E3312511BE; E3312513BE - Continued</b>			
Drive .....	22252		6471BR
<b>EGT180H335K</b>			
Deck .....	14799		6378
Traction .....	17508		6827
<b>EGT180H425K</b>			
Traction .....	17508		6827
<b>ELT115D331B</b>			
Deck .....	23710		6861
Traction .....	23626		5701
<b>ELT120G33AB</b>			
Deck .....	26546		6856
Traction .....	24039		6897
<b>ELT125D331KV</b>			
Deck .....	23710		6861
Traction .....	23626		5701
<b>ELT125G33AB</b>			
Deck .....	26546		6856
Traction .....	24039		6897
<b>ELT125G33BB</b>			
Deck .....	26546		6856
Traction .....	29641		6765BR
<b>ELT125G38AB</b>			
Deck .....	24614		6898
Traction .....	24039		6897
<b>ELT125G331K</b>			
Deck .....	23710		6861
<b>ELT140H33ABV</b>			
Deck .....	26546		6856
Traction .....	28051		6894
<b>ELT140H33BBV</b>			
Deck .....	26546		6856
Traction; 1995 .....	28334		6894
Traction; 1996 .....	28585		6896
<b>ELT140H331K</b>			
Deck .....	23710		6861
Traction .....	16724		A110
<b>ELT160H422BV</b>			
Deck .....	14799		6378
<b>EM250819BE; EM250821BE; EM281019BE; EM281021BE</b>			
Drive .....	22252		6471BR
<b>G25066; G28086SB</b>			
Drive .....	10749		6455BR
<b>GT18H334K</b>			
Deck .....	14799		6378
Traction .....	17508		6827
<b>GT18H414K</b>			
Traction .....	17508		6827
<b>GT18H484K</b>			
Deck .....	14801		6710BR
Drive .....	24497		6456BR
Traction .....	17508		6827
<b>GT180H</b>			
Deck; W/33" Deck .....	14799		6378
Primary; W/48" Deck .....	14801		6710BR
Secondary; W/48" Deck .....	24497		6456BR
Traction .....	17508		6827
<b>GT180H334K; GT180H335K</b>			
Deck .....	14799		6378
Traction .....	17508		6827
<b>GT180H414K; GT180H415K; GT180H425K</b>			
Traction .....	17508		6827
<b>GT180H425KV</b>			
Traction .....	17508		6827



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>GT180H485K</b>			
Primary .....	14801		6710BR
Secondary .....	24497		6456BR
Traction .....	17508		6827
<b>GT180H485KV</b>			
Deck .....	24497		6456BR
Drive .....	14801		6710BR
Traction .....	17508		6827
<b>GYT12333; GYT16333</b>			
Deck .....	14799		6378
<b>HM218019BE</b>			
Drive .....	22252		6471BR
<b>HT18330</b>			
Deck .....	14799		6378
Traction .....	23900		6825
<b>HT18410</b>			
Traction .....	23900		6825
<b>HT18480</b>			
Primary .....	14801		6710BR
Secondary .....	24497		6456BR
Traction .....	23900		6825
<b>HZ14330BVE</b>			
Deck .....	35389		6820BR
<b>HZ14380BVE</b>			
Deck .....	29308		6890
<b>HZ15420KVE</b>			
Deck .....	36585		6710BR
<b>HZS15422KVE</b>			
Deck .....	35389		6820BR
<b>HZS18482BVE</b>			
Deck .....	29308		6890
<b>HZT21480BV</b>			
Deck Drive .....	7011219		6745BR
Hydro. Drive .....	7075109		7026BR
<b>HZT21481BV</b>			
Deck Drive .....	7011219		6745BR
<b>LT11</b>			
Belt; W/33" Deck; W/103" Belt O.C. ....	14799		6378
Belt; W/33" Deck; W/99" Belt O.C. ....	14560		6899
Belt; W/41" Deck; W/135" Belt O.C. ....	14398		A133
<b>LT12</b>			
Belt; W/33" Deck; W/103" Belt O.C. ....	14799		6378
Belt; W/33" Deck; W/99" Belt O.C. ....	14560		6899
Belt; W/41" Deck; W/135" Belt O.C. ....	14398		A133
Belt; W/48" Deck; W/108" Belt O.C. ....	14525		6456BR
Drive .....	14801		6710BR
<b>LT12D</b>			
Belt; W/33" Deck .....	23626		5701
<b>LT12D330B; LT12D331B; LT12D331TV</b>			
Deck .....	23710		6861
Traction .....	23626		5701
<b>LT12D410B</b>			
Deck .....	14799		6378
Traction; Ser. No. 05003133 & After .....	23626		5701
<b>LT12D411B; LT12D411TV</b>			
Deck .....	14799		6378
Traction .....	23626		5701
<b>LT14H331KV</b>			
Deck .....	23710		6861
Traction .....	16724		A110
<b>LT14H411KV</b>			
Deck .....	14799		6378
Traction .....	16724		A110
<b>LT16</b>			
Belt; W/33" Deck; W/103" Belt O.C. ....	14799		6378
Belt; W/33" Deck; W/99" Belt O.C. ....	14560		6899

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>LT16 - Continued</b>			
Belt; W/41" Deck; W/135" Belt O.C. ....	14398		A133
Belt; W/48" Deck; W/108" Belt O.C. ....	14525		6456BR
Drive .....	14801		6710BR
<b>LT115D331B</b>			
Deck .....	23710		6861
Traction .....	23626		5701
<b>LT115D411B</b>			
Deck .....	14799		6378
Traction .....	23626		5701
<b>LT120D331B</b>			
Deck .....	23710		6861
Traction .....	23626		5701
<b>LT120G30AB</b>			
Deck .....	22786		6674BR
Traction .....	24039		6897
<b>LT120G30BB</b>			
Deck .....	22786		6674BR
Traction .....	29641		6765BR
<b>LT125D381B</b>			
Deck .....	24614		6898
Traction .....	23626		5701
<b>LT125G33AB</b>			
Deck .....	26546		6856
Traction .....	24039		6897
<b>LT125G33BB</b>			
Deck .....	26546		6856
Traction .....	29641		6765BR
<b>LT125G38AB</b>			
Deck .....	24614		6898
Traction .....	24039		6897
<b>LT125G38AKV</b>			
Deck .....	26688		6898
Traction .....	29641		6765BR
<b>LT125G38DB</b>			
Deck .....	35500		6775BR
Traction; Gear Model .....	29641		6765BR
Traction; Hydro. Model .....	36584		6896
<b>LT125G331K</b>			
Deck .....	23710		6861
<b>LT125G411K</b>			
Deck .....	14799		6378
<b>LT125H382KV; LT130H382KV</b>			
Deck .....	26688		6898
<b>LT140G42AKV</b>			
Deck .....	14799		6378
Traction .....	29641		6765BR
<b>LT140H33BBV</b>			
Deck .....	26546		6856
Traction; 1995 .....	28334		6894
Traction; 1996 .....	28585		6896
<b>LT140H33DBV</b>			
Deck .....	26546		6856
Traction; Gear Model .....	29641		6765BR
Traction; Hydro. Model .....	36584		6896
<b>LT140H38ABV</b>			
Deck; 1994 .....	24614		6898
Deck; 1995 .....	25042		6898
Traction; 1994 .....	28051		6894
Traction; 1995 .....	28334		6894
<b>LT140H38BBV</b>			
Deck .....	25042		6898
Traction .....	28334		6894
<b>LT140H331K</b>			
Deck .....	23710		6861
Traction .....	16724		A110

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>LT140H411K</b>			
Deck .....	14799		6378
Traction .....	16724		A110
<b>LT140H422KV</b>			
Deck .....	14799		6378
<b>LT145H33FBV</b>			
Deck .....	26546		6856
Traction .....	72657		6898
<b>LT145H38CBV</b>			
Deck .....	28793		6896
Traction .....	28585		6896
<b>LT145H38DBV</b>			
Deck .....	35500		6775BR
Traction; Gear Model .....	29641		6765BR
Traction; Hydro. Model .....	36584		6896
<b>LT145H38FBV</b>			
Deck .....	35500		6775BR
Traction .....	72657		6898
<b>LT150G42AKV</b>			
Traction .....	25042		6898
<b>LT150H38BBV</b>			
Deck .....	25042		6898
Traction .....	28334		6894
<b>LT150H422BV; LT150H422KV</b>			
Deck .....	14799		6378
<b>LT155H42BBV</b>			
Traction .....	28334		6894
<b>LT160H42CBV</b>			
Deck .....	28582		68100
Traction .....	28585		6896
<b>LT160H42CBV2</b>			
Deck .....	29205		68100
Traction .....	28585		6896
<b>LT160H42DBV; LT160H42DVB2</b>			
Deck .....	29205		68100
Traction .....	36584		6896
<b>LT160H42FBV; LT160H42FBV2</b>			
Deck .....	29205		68100
Traction .....	72657		6898
<b>LT160H422BV</b>			
Deck .....	14799		6378
<b>LT160H482BV</b>			
Primary .....	26305		6853
Secondary .....	24497		6456BR
<b>LT180H48DBV2</b>			
Deck .....	28334		6894
Drive .....	46926		6685BR
Traction .....	28585		6896
<b>LT180H48FBV2</b>			
Deck .....	28334		6894
Drive .....	46926		6685BR
Traction .....	72657		6898
<b>LT2042 (2690578)</b>			
Deck; W/42" Deck .....	1732955		6710BR
Trans.; W/42" Deck .....	1728008		6709BR
<b>LT2044 (2690579)</b>			
Arbor; W/44" Deck .....	1729627		6848BR
Trans.; W/44" Deck .....	1728008		6709BR
<b>LT2250 (2690580)</b>			
Arbor; W/50" Deck .....	1703466		6484BR
Trans.; W/50" Deck .....	1728008		6709BR
<b>LT2342</b>			
Deck Drive .....	1732955		6710BR
Trans. ....	1728008		6709BR
<b>LT2446</b>			
Deck Drive .....	1732956		6715BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>LT2446 - Continued</b>			
Trans. ....	1728008		6709BR
<b>LT12332</b>			
Deck .....	14799		6378
<b>LT12482</b>			
Primary .....	14801		6710BR
Secondary .....	24497		6456BR
<b>LT12502; LT16001; LT16002</b>			
Deck; W/33" Deck .....	14799		6378
Primary; W/48" Deck .....	14801		6710BR
Secondary; W/48" Deck .....	24497		6456BR
<b>LT16332</b>			
Deck .....	14799		6378
<b>LT16482</b>			
Primary .....	14801		6710BR
Secondary .....	24497		6456BR
<b>LT18538 (2690577)</b>			
Deck; W/38" Deck .....	1732204		6524BR
Trans.; W/38" Deck .....	1728008		6709BR
<b>LT23460 AWS</b>			
Primary .....	1727869		6798BR
Secondary .....	720404		6475BR
Trans. ....	7101794		6474BR
<b>LTD Series</b>			
Belt; W/41" Deck .....	14799		6378
<b>M25089TE; M28128BE; M33148KVE</b>			
Drive .....	18236		6471BR
<b>M250819BE; M250821BE; M280817B;</b>			
<b>M280917B; M280917BE; M280919B;</b>			
<b>M280921B; M281019BE; M281021BE;</b>			
<b>M300917B</b>			
Drive .....	22252		6471BR
<b>M300917BE; M300919B; M300919BE;</b>			
<b>M300921B; M300921BE; M301019BE;</b>			
<b>M301021BE</b>			
Drive .....	22252		6471BR
<b>MZM2200KH Pro Cruiser</b>			
Deck; W/52" Deck .....	42776		B118
Drive; W/52", 61" Deck .....	35543		②6837
Traction; W/52", 61" Deck .....	45254		②6834
<b>N250816B; N250816BE</b>			
Drive .....	22252		6471BR
<b>N281016BE</b>			
Drive; Early .....	44637		6975
Drive; Late .....	43844		6635BR
<b>NLT120G30DB</b>			
Deck .....	22786		6674BR
Traction; Gear Model .....	29641		6765BR
Traction; Hydro. Model .....	36584		6896
<b>NZM19483KWW</b>			
Hydro. Drive .....	7075109		7026BR
<b>NZM21523KWW; NZM25523KWW</b>			
Hydro. Drive .....	7075109		7026BR
Secondary Drive .....	7029266		6728BR
<b>NZM25613KWW; NZM27613KH</b>			
Hydro. Drive .....	7075109		7026BR
Primary Drive .....	7071766		6877BR
<b>NZMJ23523KH</b>			
Hydro. Drive .....	7075109		7026BR
Secondary Drive .....	7029266		6728BR
<b>NZMJ25613KH</b>			
Hydro. Drive .....	7075109		7026BR
Primary Drive .....	7071766		6877BR
<b>R25089TE; R25089TVE</b>			
Drive .....	18236		6471BR

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
R250811BE; R281213BE; R2811511BE; R3312511BE; R3312513BE	Deck ..... 14525 Drive ..... 22252		6456BR 6471BR
RER11528; RER12528	Deck Drive ..... 7022252		6471BR
RER13530	Trans. .... 1707346		6842
RER17533	Deck Drive ..... 7043844		6635BR
RLT115D331B	Deck ..... 23710 Traction ..... 23626		6861 5701
RLT125G38AKV	Deck ..... 26688 Traction ..... 29641		6898 6765BR
RLT125G331K	Deck ..... 23710		6861
RLT140H331K	Deck ..... 23710 Traction ..... 16724		6861 A110
RLT140H422KV; RYT16D334K	Deck ..... 14799		6378
S50XB2648	Deck Drive ..... 5101301 Hydro. Drive ..... 5022173		6567BR 6743BR
S50XKAV1936	Deck Drive ..... 5101121 Hydro. Drive ..... 5022173		6877BR 6743BR
S50XKAV1948	Deck Drive ..... 5101301 Hydro. Drive ..... 5022173		6567BR 6743BR
S50XKAV2036	Deck Drive ..... 5101121 Hydro. Drive ..... 5022173		6877BR 6743BR
S50XKAV2048	Deck Drive ..... 5101301 Hydro. Drive ..... 5022173		6567BR 6743BR
S50XTB2436; S50XTB2536	Deck Drive ..... 5021650 Hydro. Pump ..... 5022173		6665BR 6743BR
S50XTB2548; S50XTB2748	Deck Drive ..... 5101301 Hydro. Pump ..... 5022173		6567BR 6743BR
S50XTKAV1936	Deck Drive ..... 5021650 Hydro. Pump ..... 5022173		6665BR 6743BR
S50XTKAV1948	Deck Drive ..... 5101301 Hydro. Pump ..... 5022173		6567BR 6743BR
S75XKAV2252	Blade Drive ..... 5102035 Eng. To Deck ..... 5102040		6858BR 6615BR
S75XKAV2352	Blade Drive ..... 5102035 Eng. To Deck ..... 5102040 Hydro. Pump ..... 5100555		6858BR 6615BR 6772BR
S75XKAV2652	Blade Drive ..... 5102035 Eng. To Deck ..... 5102040		6858BR 6615BR
S125XTBV2552	Deck Drive ..... 5103927 Hydro. Drive ..... 5103919		7000BR 6757BR
S125XTBV2761	Deck Drive ..... 5103871 Hydro. Drive ..... 5103919		6938BR 6757BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
S125XTKAV2352	Deck Drive ..... 5103927 Hydro. Drive ..... 5103919		7000BR 6757BR
S125XTKAV2461	Deck Drive ..... 5103871 Hydro. Drive ..... 5103919		6938BR 6757BR
S150XKAV2048; S150XKAV2148	Deck Drive ..... 5023297 Hydro. Drive ..... 5100923		6767BR 6482BR
S150XKAV2252; S150XKAV2552	Deck Drive ..... 5023435 Hydro. Drive ..... 5100923		6768BR 6482BR
S150XKOH2348	Deck Drive ..... 5023297 Hydro. Drive ..... 5100923		6767BR 6482BR
S150XKOH2752	Deck Drive ..... 5023435 Hydro. Drive ..... 5100923		6768BR 6482BR
S150XTB2648	Deck Drive ..... 5023297 Hydro. Pump ..... 5102767		6767BR 6996BR
S150XTB2852	Deck Drive ..... 5103395 Hydro. Pump ..... 5102767		6936BR 6996BR
S150XTBV2648	Deck Drive ..... 5103392 Hydro. Pump ..... 5102767		6999BR 6996BR
S150XTBV2652	Deck Drive ..... 5103872 Hydro. Pump ..... 5102767		6936BR 6996BR
S150XTKAV2448	Deck Drive ..... 5023297 Hydro. Pump ..... 5102767		6767BR 6996BR
S150XTKAV2452	Deck Drive ..... 5103395 Hydro. Pump ..... 5102767		6936BR 6996BR
S175XY20D52; S175XY24D61	Deck Drive; W/Rear Discharge ..... 5102269 Deck Drive; W/Side Discharge ..... 5101825 Hydro. Pump ..... 5102272 P.T.O. .... 5102038		6880BR 6902BR 7035BR ②7010BR
S200XBV32	Deck Drive; W/61" Deck ..... 5100893 Deck Drive; W/72" Deck ..... 5022399 Hydro. Drive ..... 5101029		6747BR 6722BR 6630BR
S200XKAV2561; S200XKAV2661; S200XKAV2761; S200XKOH2761	Deck Drive ..... 5100893 Hydro. Drive ..... 5101029		6747BR 6630BR
S200XTB2761	Deck Drive ..... 5103870 Hydro. Pump ..... 5102013		6937BR 6506BR
S200XTB2861; S200XTB3061	Deck Drive ..... 5103390 Hydro. Pump ..... 5102013		6937BR 6506BR
S200XTB3072	Deck Drive ..... 5100423 Hydro. Pump ..... 5102013		7111BR 6506BR
S200XTBV2861	Deck Drive ..... 5100893 Hydro. Drive ..... 5101029		6747BR 6630BR
S200XTBV3261	Deck Drive ..... 5103390 Hydro. Pump ..... 5102013		6937BR 6506BR
S200XTBV3272	Deck Drive ..... 5100423 Hydro. Pump ..... 5102013		7111BR 6506BR

②Two Required

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>S200XTBV3661</b>			
Deck Drive .....	5103390		6937BR
Hydro. Pump .....	5102013		6506BR
<b>S200XTBV3672</b>			
Deck Drive .....	5100423		7111BR
Hydro. Pump .....	5102013		6506BR
<b>S200XTBVP3261; S200XTKAV2661</b>			
Deck Drive .....	5103390		6937BR
Hydro. Pump .....	5102013		6506BR
<b>S200XTKOH2961</b>			
Deck Drive .....	5103397		7111BR
Hydro. Pump .....	5102013		6506BR
<b>S800XBV31</b>			
Deck Drive; W/61" Deck .....	5021854		6946BR
Deck Drive; W/72" Deck .....	5022435		6933BR
Hydro. Drive; Ser. No. 2014013368 & Before .....	5101248		Ⓜ6674BR
Hydro. Drive; Ser. No. 2014013369 & After .....	5102695		Ⓜ6820BR
P.T.O. ....	5101179		Ⓜ6974BR
<b>S800XKAV28</b>			
Deck Drive; W/61" Deck .....	5021854		6946BR
Hydro. Drive; Ser. No. 2014013368 & Before .....	5101248		Ⓜ6674BR
Hydro. Drive; Ser. No. 2014013369 & After .....	5102695		Ⓜ6820BR
P.T.O. ....	5101179		Ⓜ6974BR
<b>S800XY30D</b>		9400	
Alt. ....	5101985X5		9400HD
Deck Drive; W/61" Deck .....	5021854		6946BR
Deck Drive; W/72" Deck .....	5022435		6933BR
P.T.O. ....	5102594		Ⓜ7004BR
Pump Drive .....	5102039		7023BR
<b>SPX2146</b>			
Deck Drive .....	1732956		6715BR
Trans. ....	1728008		6709BR
<b>SPX2452</b>			
Deck Drive .....	1736516		6727BR
Trans. ....	1728008		6709BR
<b>W280923B; W301023BVE</b>			
Drive .....	43844		6635BR
<b>WM280921B; WM301021BE</b>			
Drive .....	22252		6471BR
<b>YT12D</b>			
Deck; W/33" Deck .....	14799		6378
Primary; W/48" Deck .....	14801		6710BR
Secondary; W/48" Deck .....	24497		6456BR
<b>YT12D334B</b>			
Deck .....	14799		6378
<b>YT16D</b>			
Deck; W/33" Deck .....	14799		6378
Primary; W/48" Deck .....	14801		6710BR
Secondary; W/48" Deck .....	24497		6456BR
<b>YT16D334B; YT16D334K</b>			
Deck .....	14799		6378
<b>YT16D484; YT16D484B</b>			
Primary .....	14801		6710BR
Secondary .....	24497		6456BR
<b>YT16D484K</b>			
Deck .....	24497		6456BR
Drive .....	14801		6710BR
<b>YT18H</b>			
Deck; W/33" Deck .....	14799		6378
Primary; W/48" Deck .....	14801		6710BR
Secondary; W/48" Deck .....	24497		6456BR
Traction .....	23900		6825
<b>YT18H334K</b>			
Deck .....	14799		6378
Traction .....	23900		6825

ⓂTwo Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>YT18H414K</b>			
Traction .....	23900		6825
<b>YT18H484K</b>			
Primary .....	14801		6710BR
Secondary .....	24497		6456BR
Traction .....	23900		6825
<b>YT12333; YT16333</b>			
Deck .....	14799		6378
<b>YT16483</b>			
Primary .....	14801		6710BR
Secondary .....	24497		6456BR
<b>YZ13331BE</b>			
Deck .....	35389		6820BR
Drive .....	29117		6950
Hydro. ....	41823		6842
<b>YZ13381BE</b>			
Deck .....	29308		6890
Drive .....	29117		6950
Hydro. ....	41823		6842
<b>Z1202B; Z1203B</b>			
Eng. To Deck .....	79780		B106
Hydro. ....	79776		6873
<b>Z1402K</b>			
Cross Deck .....	79778		6524BR
Eng. To Deck .....	79779		6702BR
Hydro. ....	79776		6873
<b>Z1404K</b>			
Cross Deck .....	79778		6524BR
Eng. To Deck .....	79779		6702BR
Hydro. ....	62465		6882
<b>Z1802K</b>			
Cross Deck; W/42" Deck .....	79778		6524BR
Cross Deck; W/48" Deck .....	79777		6653BR
Eng. To Deck; W/42", 48" Deck .....	79779		6702BR
Hydro.; W/42", 48" Deck .....	79776		6873
<b>Z1804K</b>			
Cross Deck; W/42" Deck .....	79778		6524BR
Cross Deck; W/48" Deck .....	79777		6653BR
Eng. To Deck; W/42", 48" Deck .....	79779		6702BR
<b>Z1805K</b>			
Cross Deck; W/48" Deck .....	79777		6653BR
Cross Deck; W/60" Deck .....	79186		6633BR
Eng. To Deck; W/48" Deck .....	79779		6702BR
Eng. To Deck; W/60" Deck .....	79781		6866BR
Main Drive; W/48", 60" Deck .....	62465		6882
<b>Z2002K</b>			
Cross Deck; W/42" Deck .....	79778		6524BR
Cross Deck; W/48" Deck .....	79777		6653BR
Cross Deck; W/60" Deck .....	79186		6633BR
Eng. To Deck; W/42", 48" Deck .....	79779		6702BR
Eng. To Deck; W/60" Deck .....	79781		6866BR
Hydro.; W/42", 48", 60" Deck .....	79776		6873
<b>Z2004K</b>			
Cross Deck; W/42" Deck .....	79778		6524BR
Cross Deck; W/48" Deck .....	79777		6653BR
Cross Deck; W/60" Deck .....	79186		6633BR
Eng. To Deck; W/42", 48" Deck .....	79779		6702BR
Eng. To Deck; W/60" Deck .....	79781		6866BR
Hydro.; W/42", 48", 60" Deck .....	62465		6882
<b>Z2205KV</b>			
Cross Deck; W/48" Deck .....	79777		6653BR
Cross Deck; W/60" Deck .....	79186		6633BR
Eng. To Deck; W/48" Deck .....	79779		6702BR
Eng. To Deck; W/60" Deck .....	79781		6866BR
<b>ZF2100DKU</b>			
Deck Drive; W/52", 61" Deck .....	41830		Ⓜ6837
Driveshaft To Hydro.; W/52", 61" Deck .....	35544		Ⓜ6834
<b>ZF2200K</b>			
Deck Drive; W/61" Deck .....	35543		Ⓜ6837
Driveshaft - Upper; W/61" Deck .....	35544		Ⓜ6834





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>ZF2300GKU Turf Cruiser</b>			
Deck Drive; W/52", 61", 73" Deck	41830		②6837
Driveshaft To Hydro.; W/52", 61", 73" Deck	35544		②6834
<b>ZF2500K</b>			
Deck Drive; W/52", 61" Deck	35543		②6837
Driveshaft - Upper; W/52", 61" Deck	35544		②6834
<b>ZF2500KH Turf Cruiser</b>			
Deck Drive; W/52", 61", 73" Deck	35543		②6837
Driveshaft - Upper; W/52", 61", 73" Deck	35544		②6834
<b>ZM2200K; ZM2500KH Pro Cruiser</b>			
Drive; W/52", 61" Deck	35543		②6837
Traction; W/52", 61" Deck	45254		②6834
<b>ZT2042 (2690645)</b>			
Eng. To Deck; W/42" Deck	1732966		6765BR
Trans.; W/42" Deck	1732224		6697BR
<b>ZT2142</b>			
Deck Drive	1732966		6765BR
Hydro. Drive	1732224		6697BR
<b>ZT2446</b>			
Deck Drive	5102145		6708BR
Hydro. Drive	5101033		6637BR
<b>ZT2450 (2690647)</b>			
Arbor; W/50" Deck	1732204		6524BR
Trans.; W/50" Deck	1732224		6697BR
<b>ZT2648</b>			
Deck Drive	5101301		6567BR
Hydro. Drive	5022173		6743BR
<b>ZT2650</b>			
Blade Drive	1732204		6524BR
Hydro. Drive	1732224		6697BR
<b>ZT2652</b>			
Hydro. Drive	7100102		6871BR
<b>ZT2654</b>			
Hydro. Drive	5101033		6637BR
<b>ZT2746</b>			
Deck Drive	7103788		6707BR
Hydro. Drive	7100102		6871BR
<b>ZT18533</b>			
Deck Drive	7102246		6675BR
Hydro. Drive	1732224		6697BR
<b>ZU2013K</b>			
Deck; W/48" Deck	79182		A105
Deck; W/60" Deck	79186		6633BR
Eng. To Deck; W/48" Deck	79563		6987
Eng. To Deck; W/60" Deck	62065		6990
<b>ZU2014K</b>			
Cross Deck; W/48" Deck	79777		6653BR
Cross Deck; W/60" Deck	79186		6633BR
Eng. To Deck; W/48" Deck	62065		6990
Primary Drive; W/48", 60" Deck	62321		6844
Secondary Drive; W/48", 60" Deck	62322		6877
<b>SOUTHLAND</b>			
<b>RR245; RR254; RR255</b>			
Belt; W/25" Belt O.C.	RR705	3250	6925
Belt; W/44" Belt O.C.	RR703	2440	6844
<b>SPARTAN MOWERS</b>			
<b>RT HD; RT Pro</b>			
Deck Drive; W/54" Deck	461-0001-00		6983BR
Deck Drive; W/61" Deck	461-0002-00		7049BR
Deck Drive; W/72" Deck	461-0003-00		6860BR
Pump	461-0004-00		7013BR
<b>RZ Pro</b>			
Deck Drive; W/54" Deck	461-0001-00		6983BR
Deck Drive; W/61" Deck	461-0002-00		7049BR
Pump	461-0004-00		7013BR

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SPARTAN MOWERS - Continued</b>			
<b>SRT HD; SRT Pro; SRT XD</b>			
Deck Drive; W/54" Deck	461-0001-00		6983BR
Deck Drive; W/61" Deck	461-0002-00		7049BR
Deck Drive; W/72" Deck	461-0003-00		6860BR
Pump	461-0005-00		6861BR
<b>SPEDEX</b>			
<b>820</b>			
Drive; W/Sliding Eng.	3926964		6964
<b>832D</b>			
Drive	3926974		6974
Hyd. Pump	3912400		6840
<b>840</b>			
Drive; W/Stationary Eng.	3926831		6983
<b>1020; 1030</b>			
Drive; W/Sliding Eng.	3926964		6964
<b>1040; 1040A</b>			
Drive; W/Stationary Eng.	3926831		6983
<b>1130</b>			
Drive; W/Sliding Eng.	3926964		6964
<b>1140; 1240</b>			
Drive; W/Stationary Eng.	3926831		6983
<b>1320; 1420; 1430; 1630</b>			
Drive; W/Sliding Eng.	3926964		6964
<b>1630T</b>			
Drive; W/Sliding Eng.	3926968		6968
<b>1632</b>			
Drive	3926967		6967
Hyd. Pump	3916834		6834
<b>1640</b>			
Drive; W/Stationary Eng.	3926831		6983
<b>1682</b>			
Drive	3926967		6967
<b>1832</b>			
Drive; W/Sliding Eng.	3926967		6967
Hyd. Pump	3916340		6832
<b>2022</b>			
Eng. To Deck Drive			6938
<b>Eagle</b>			
Drive			6983
<b>S14</b>			
Drive	3926963		6963
<b>S17</b>			
Drive; W/Sliding Eng.	3926964		6964
Drive; W/Stationary Eng.	3926943		6943
<b>S18</b>			
Drive; W/Sliding Eng.	3926964		6964
<b>S19</b>			
Drive; W/Stationary Eng.	3926831		6983
<b>S23; S24</b>			
Drive; W/Sliding Eng.	3926964		6964
<b>S24VS</b>			
Drive; W/Stationary Eng.	3926947		6947
<b>S32</b>			
Drive	3926960		6996
P.T.O.	3926933		6933
<b>SPEIGEL</b>			
<b>133-434; 133-640</b>			
Blade	7540127		6966
Drive; W/25" Belt O.C.	7540135		6925
Drive; W/31" Belt O.C.	7540136		6931
<b>136-485</b>			
Blade	7540151		6967
Trans.	7540191		6865

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SPEIGEL - Continued</b>			
<b>140-760</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>146-672</b>			
Blade ....	7540184		6852
Deck ....	7540180		6510BR
Trans. ....	7540182	3810	6981
<b>SPIRIT II</b>			
<b>1130; 1230</b>			
Blade ....			A110
P.T.O. ....			6850
Trans. ....	360237		6834
<b>SPRINGFIELD</b>			
<b>60A-1</b>			
Blade ....	60A34		6932
<b>60AMR</b>			
Blade ....	60F100		6828
Eng. To Trans. ....	60F99		6869
<b>61A; 61AB</b>			
Blade ....	60A34		6932
<b>61D; 61DE</b>			
Blade ....	60A34		6932
Eng. To J.S. ....	61D19		6843
J.S. To Trans. ....	61D15		6826
<b>61VRB; 61VRC</b>			
Belt; W/32" Belt O.C. ....	61V38		6732
<b>62A; 62AB</b>			
Blade ....	60A34		6932
<b>62D; 62DE</b>			
Blade ....	60A34		6932
Eng. To J.S. ....	61D19		6843
J.S. To Trans. ....	61D15		6826
<b>63A</b>			
Blade ....	60A34		6932
<b>63D; 63DE</b>			
Blade ....	60A34		6932
Eng. To J.S. ....	61D19		6843
J.S. To Trans. ....	61D15		6826
<b>64A; 64D; 64DE</b>			
Blade ....	60A34		6932
<b>65LT6; 65LT6E</b>			
Blade ....	60A34		6932
Eng. To J.S. ....	61D19		6843
Trans. To J.S. ....	61D15		6826
<b>66CTM; 66CTME</b>			
Blade ....	66CT257		3V670
Eng. ....	61TR83	2310	6831
Starter/Gen. ....	61TR304	7320	
<b>3001HR</b>			
Drive ....	2137	3440	6944
Reverse ....	2170	2170	6817
<b>3002H; 3003H; 3004H</b>			
Belt; W/35" Belt O.C. ....	2422B	3350	6935
Belt; W/46" Belt O.C. ....	2138	3460	6946
Belt; W/57" Belt O.C. ....	3317	3570	6957
Reverse ....			6817
Starter/Gen. ....	61TR304	7320	
<b>3005HR</b>			
Drive ....	2137	3440	6944
Reverse ....	2170	2170	6817
<b>AMR49; EC59; EC63C; EC64C; EC65LT</b>			
Belt; W/35" Belt O.C. ....	59080		6835
<b>STEINER TURF</b>			
<b>2X4</b>			
Broom Attachment ....			6844

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>STEINER TURF - Continued</b>			
<b>2X4 - Continued</b>			
Flail Mower Attachment .....			6844
Mower Deck Attachment .....			6844
Power Blower Attachment .....			6844
Reel Attachment .....			6847
Snow Blower Attachment .....			6857
Tiller Attachment .....			6844
<b>4X4</b>			
Attachment Drive; W/41" Belt O.C. ....	81A039		6841
Attachment Drive; W/42" Belt O.C. ....	81A040		6842
Broom Attachment .....	A40		6842
Flail Mower Attachment .....	A40		6842
Loader Attachment .....			6828
Mower Deck Attachment .....	A40		6842
Power Blower Attachment .....	A40		6842
Power Edger Attachment .....			6877
Reel Attachment .....			6845
Snow Blower Attachment .....	A53		6855
Tiller Attachment .....	A40		6842
<b>220</b>			
Attachment Drive; W/Kubota WG600-B			
Eng. ....	A40		6842
Deck; W/MX40 Deck; W/Kubota			
WG600-B Eng. ....	81B158		B158
Fan & Alt.; W/Kubota WG600-B Eng. ....	REMF1320	7320	
P.T.O.; W/2WD; W/Kubota WG600-B			
Eng.; W/1/2" Belt T.W. ....	81A034		6836
P.T.O.; W/2WD; W/Kubota WG600-B			
Eng.; W/21/32" Belt T.W. ....	85360		6936
<b>410</b>			
Drive .....	81A040		6842
P.T.O. ....			6942
<b>420</b>			
P.T.O.; W/4WD .....	81A038		6839
<b>425</b>			
P.T.O. ....	81A042		6844
<b>525</b>			
Attachment Drive; W/Kubota 90S Eng. ...	81B041		6944
Fan & Alt.; W/Kubota 90S Eng. ....		7375	
P.T.O.; W/Kubota 90S Eng. ....			6945
<b>720</b>			
Attachment Drive .....	81A055		6857
Drive; W/Packer Drive .....	81A035		6837
Eng. To Pump .....	81A041		6843
Mower Clutch .....	81A041		6843
<b>D16</b>			
Eng. To Pulley; Ser. No. AGN231 .....			6840
Pulley To Hyd. Pump; Ser. No.			
AGN231 .....			6849
<b>MPV</b>			
Broom Attachment .....			6849
Flail Mower Attachment .....			6849
Mower Deck Attachment .....			6849
Power Blower Attachment .....			6849
Snow Blower Attachment .....			6861
Tiller Attachment .....			6849
<b>Paraplegic</b>			
Drive .....	81A105		68107
Mower Attachment; W/48" Deck .....	81A128		A128
Mower Attachment; W/60" Deck .....	81A144		A144
Mower Attachment; W/72" Deck .....	81A180		A180
<b>S18</b>			
P.T.O. To Deck .....	81A40		6842
<b>S20</b>			
Fan & Alt. ....	REMF1350	7350	
P.T.O. ....	81A38		6840
P.T.O. To Deck .....	81A40		6842
<b>Three Wheeler</b>			
P.T.O. To Tiller .....	81A47		6849
<b>Turfmaster</b>			
Belt; W/48" Deck .....	81A128		A128



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>STEINER TURF - Continued</b>			
<b>Turfmaster – Continued</b>			
Belt; W/60" Deck	81A144		A144
Belt; W/72" Deck	81A180		A180
P.T.O.; W/49" Belt O.C.	81A47		6849
P.T.O.; W/70" Belt O.C.	81A68		6870
<b>SUNBEAM CORP.</b>			
<b>RR100</b>			
Belt	4638		6830
<b>RR500</b>			
Drive	11144		6835
Trans.			6852
<b>SUNSHINE</b>			
<b>E-Z Roll</b>			
Drive; W/12 H.P. Eng.	R9084		6986
<b>SWISHER</b>			
<b>Ride King</b>			
Deck			6850
Eng. To J.S.		2490	6849
J.S. To Wheel Drive		2230	6823
<b>TWR10532BS</b>			
Drive	37X129		6830
<b>Z2460CPKA</b>			
Blade Drive	18637		6820BR
Eng. To Deck	18746		6484BR
Hydro. Drive	18811		6523BR
<b>Z2466CPKA; Z3166CPKA</b>			
Blade Drive	19070		6793BR
Eng. To Deck	19069		7089BR
Hydro. Drive	18811		6523BR
<b>Z21554CPHO</b>			
Eng. To Deck	18787		6777BR
Hydro. Drive	18811		6523BR
<b>Z21560CPHO</b>			
Blade Drive	18637		6820BR
Eng. To Deck	18746		6484BR
Hydro. Drive	18811		6523BR
<b>ZT1436B; ZT2250</b>			
Hydro. Drive	66LR		6819BR
<b>ZT2350A; ZT2450A</b>			
Deck Drive	12881		A100
Eng. To Deck	10263		6811BR
Hydro. Drive	6046		7052BR
<b>ZT2452</b>			
Deck Drive	BA116		A116
Eng. To Deck	13081		6976BR
Hydro. Drive	6046		7052BR
<b>ZT2454</b>			
Deck Drive	037X66		A45
Eng. To Deck	10263		6811BR
Hydro. Drive	14451		6810BR
<b>ZT2560; ZT2660B</b>			
Deck Drive	5058		6777BR
Eng. To Deck	10263		6811BR
Hydro. Drive	6046		7052BR
<b>ZT2760BP</b>			
Deck Drive	037X66		A45
Eng. To Deck	5058		6777BR
Hydro. Drive	14453		6757BR
<b>ZT2760KP</b>			
Deck Drive	037X66		A45
Eng. To Deck	12527		A128
Hydro. Drive	14454		6758BR
<b>ZT2766</b>			
Deck Drive	12527		A128
Eng. To Deck	037X89		6476BR
Hydro. Drive	6046		7052BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SWISHER - Continued</b>			
<b>ZT2766BP; ZT2766KP</b>			
Deck Drive	037X66		A45
Eng. To Deck	12527		A128
Hydro. Drive	14454		6758BR
<b>ZT18542</b>			
Hydro. Drive	66LR		6819BR
<b>ZTR2354KA</b>			
Eng. To Deck	18787		6777BR
Hydro. Drive	18811		6523BR
<b>ZTR2360KA</b>			
Blade Drive	18637		6820BR
Eng. To Deck	18746		6484BR
Hydro. Drive	18811		6523BR
<b>ZTR2366KA</b>			
Blade Drive	19070		6793BR
Eng. To Deck	19069		7089BR
Hydro. Drive	18811		6523BR
<b>ZTR2454BS</b>			
Eng. To Deck	18787		6777BR
Hydro. Drive	18811		6523BR
<b>TORO</b>			
<b>8-25</b>			
Blade; Model No. 56128, 56129, 56132, 56133, 70040, 70060	671390		6583BR
Blade; Model No. 70041, 70044, 70060, 70122	980710		6583BR
<b>8-32</b>			
Blade; Model No. 56145, 56185	471420		6559BR
Blade; Model No. 70042	920875		6858
Traction; Model No. 56145, 56185	471410		6224
Traction; Model No. 70042	920870		6831
<b>10-32</b>			
Blade; Model No. 56165, 56190	471420		6559BR
Blade; Model No. 70080, 70100	920875		6858
Traction; Model No. 56165, 56190	471410		6224
Traction; Model No. 70080, 70100	920870		6831
<b>10-32XL</b>			
Blade; Model No. 71140	88-6260		6851
Traction; Model No. 71140	88-6270		6861
<b>11-32</b>			
Blade; Model No. 70081, 70142	920875		6858
Traction; Model No. 70081, 70142	920870		6831
<b>12-32</b>			
Blade; Model No. 56175, 56176, 56177, 56195	471420		6559BR
Blade; Model No. 57450	285250		6853
Blade; Model No. 70082, 70084, 70089, 70120, 70140, 70141	920875		6858
Deck; W/12 H.P. Eng.; W/32" Blade	471420		6559BR
Traction; Model No. 56175, 56176, 56177, 56195	471410		6224
Traction; Model No. 57450	282650		A100
Traction; Model No. 70082, 70084, 70089, 70120, 70140, 70141	920870		6831
<b>12-32E</b>			
Blade; Model No. 70171	920875		6858
Traction; Model No. 70171	920870		6831
<b>12-32XL</b>			
Blade; Model No. 71182, 71188, 71189, 71199, 71200, 71201	88-6260		6851
Traction; Model No. 71182, 71200	88-6270		6861
Traction; Model No. 71188, 71189, 71199, 71201	94-4291		6899
<b>12-38HXL</b>			
Blade; Model No. 71181, 71203	88-6250		6627BR
Traction; Model No. 71181, 71203	88-6280		6884
<b>12-38XL</b>			
Blade; Model No. 71180, 71184, 71202	88-6250		6627BR
Traction; Model No. 71180	88-6280		6884
Traction; Model No. 71184, 71202	886240		6895

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>13-32</b>			
Blade; Model No. 70131, 70183 .....	920875		<b>6858</b>
Traction; Model No. 70131, 70183 .....	920870		<b>6831</b>
<b>13-32XL</b>			
Blade; Model No. 70201, 71209 .....	88-6260		<b>6851</b>
Traction; Model No. 70201, 71209 .....	94-4291		<b>6899</b>
<b>13-38HXL</b>			
Blade; Model No. 71191 .....	88-6250		<b>6627BR</b>
Traction; Model No. 71191 .....	88-6280		<b>6884</b>
<b>13-38XL</b>			
Blade; Model No. 71185, 71190, 71191, 71205, 71208, 71213 .....	88-6250		<b>6627BR</b>
Traction; Model No. 71185, 71190, 71208 .....	88-6270		<b>6861</b>
Traction; Model No. 71191, 71213 .....	88-6280		<b>6884</b>
Traction; Model No. 71205; Ser. No. 5900001-5999999 .....	886240		<b>6895</b>
Traction; Model No. 71205; Ser. No. 6900001-6999999 .....	88-6270		<b>6861</b>
<b>14-38HXL</b>			
Blade; Model No. 71193, 71215, 71219 .....	88-6250		<b>6627BR</b>
Hydro; Model No. 71193, 71215, 71219 .....	88-6280		<b>6884</b>
<b>14-38XL</b>			
Blade; Model No. 71198, 71215, 71217, 71220 .....	88-6250		<b>6627BR</b>
Traction; Model No. 71198, 71220 .....	88-6270		<b>6861</b>
Traction; Model No. 71215, 71217 .....	88-6280		<b>6884</b>
<b>15-38HXL</b>			
Blade; Model No. 71221, 71240 .....	88-6250		<b>6627BR</b>
Traction; Model No. 71221, 71240 .....	88-6280		<b>6884</b>
<b>15-44HXL</b>			
Hydro; Model No. 71192, 71196, 71218 .....	933883		<b>6463BR</b>
<b>16-38HXL</b>			
Blade; Model No. 71225 .....	88-6250		<b>6627BR</b>
Traction; Model No. 71225 .....	88-6280		<b>6884</b>
<b>16-38HXL</b>			
Blade; Model No. 71241 .....	88-6250		<b>6627BR</b>
Traction; Model No. 71241 .....	88-6280		<b>6884</b>
<b>16-38XL</b>			
Blade; Model No. 71223 .....	88-6250		<b>6627BR</b>
Traction; Model No. 71223 .....	88-6270		<b>6861</b>
<b>16-38XLE</b>			
Blade; Model No. 71226 .....	88-6250		<b>6627BR</b>
Traction; Model No. 71226 .....	88-6270		<b>6861</b>
<b>16-44HXL</b>			
Hydro; Model No. 71196, 71197, 71218 .....	933883		<b>6463BR</b>
<b>16-44HXL</b>			
Hydro; Model No. 71280 .....	933883		<b>6463BR</b>
<b>110-4</b>			
Drive; Model No. R3-10B403, R3-10B404 .....	113105		<b>6833</b>
P.T.O.; Model No. R3-10B403, R3-10B404 .....	114231		<b>6841</b>
Spindle; Model No. R3-10B403, R3-10B404 .....	114567		<b>6927BR</b>
<b>112-6</b>			
Drive; Model No. R3-12B601, R3-12B602 .....	113105		<b>6833</b>
P.T.O.; Model No. R3-12B601, R3-12B602 .....	114231		<b>6841</b>
Spindle; Model No. R3-12B601, R3-12B602 .....	114567		<b>6927BR</b>
<b>120</b>			
Deck; W/52" Deck .....	565570		<b>6854</b>
Eng. Fan .....	98-9008		<b>6698BR</b>
Eng. To Spindle .....	541380		<b>6874</b>

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>210-5</b>			
Blade; W/10 H.P. Eng. ....	113288		<b>6853</b>
Drive; Model No. 31-10B501 .....	114433		<b>A81</b>
Drive; Model No. 31-10B502, 31-10B503 .....	114860		<b>6714BR</b>
Trans. To Deck; W/10 H.P. Eng. ....	114860		<b>6714BR</b>
<b>210-H</b>			
Drive; Model No. 31-10BE01, 31-10BE02 .....	114433		<b>A81</b>
<b>210-H Hydro</b>			
Deck; W/10 H.P. Eng. ....	114421		<b>6854</b>
Trans.; W/10 H.P. Eng. ....	114433		<b>A81</b>
<b>212-5</b>			
Deck; W/12 H.P., 5-Speed Eng. ....	114860		<b>6714BR</b>
Drive; Model No. 32-12O501 .....	114433		<b>A81</b>
Drive; Model No. 32-12O503 .....	114860		<b>6714BR</b>
Drive; Model No. 32-12O5A1 .....	114433		<b>A81</b>
Drive; Model No. R2-12B502, R2-12O501, 32-12B5A2, 32-12B5A3, 32-12O502 .....	114860		<b>6714BR</b>
Drive; Model No. R2-12O502; Ser. No. 2900001-2999999 .....	114860		<b>6714BR</b>
Spindle; Model No. S2-12B602 .....	114421		<b>6854</b>
Spindle; W/50" Deck; Model No. R2-12O502; Ser. No. 3900001-3999999 .....	113625		<b>B103</b>
Spindle; W/60" Deck; Model No. R2-12O502; Ser. No. 3900001-3999999 .....	112449		<b>B128</b>
<b>212-H</b>			
Deck; W/50" Deck; Model No. R2-12O502; Ser. No. 3900001-3999999 .....	113625		<b>B103</b>
Deck; W/60" Deck; Model No. R2-12O502; Ser. No. 3900001-3999999 .....	112449		<b>B128</b>
Drive; Model No. 32-12OEA1, 32-12OEA01, 32-12OEA02, 32-12OEA03 .....	114433		<b>A81</b>
Drive; Model No. R2-12OEA01, 32-12BEA2, 32-12BEA3 .....	114433		<b>6883</b>
Drive; Model No. R2-12OEA02; Ser. No. 2900001-2999999 .....	114433		<b>A81</b>
P.T.O.; Model No. R2-12OEA01 .....	115968		<b>6899</b>
P.T.O.; Model No. R2-12OEA02; Ser. No. 2900001-2999999 .....	115968		<b>6899</b>
<b>212-H Hydro</b>			
Cross Drive; W/12 H.P. Eng. ....	113141		<b>6876</b>
Deck; W/12 H.P. Eng. ....	114433		<b>A81</b>
<b>216-H</b>			
Drive; Model No. 32-16BE01 .....	114433		<b>A81</b>
<b>216-H Hydro</b>			
Cross Drive; W/16 H.P. Eng. ....	113141		<b>6876</b>
Deck; W/16 H.P. Eng. ....	114433		<b>A81</b>
<b>223-D</b>			
Eng. ....	928876		<b>6739</b>
Eng. To Deck .....	63-6240		<b>6808BR</b>
<b>224</b>			
Eng. ....	928879		<b>6737</b>
Eng. To Deck .....	63-6240		<b>6808BR</b>
W.P. ....	67-4410		<b>6735</b>
<b>225</b>			
Eng. To Deck .....	63-6240		<b>6808BR</b>
Fan & W.P. ....	99-9156	<b>7370</b>	
<b>227-S</b>			
Drive; Model No. R2-17K502 .....	108427		<b>6463BR</b>
<b>228-D</b>			
Eng. To Deck .....	63-6240		<b>6808BR</b>
<b>244-5</b>			
Deck; W/14 H.P., 5-Speed Eng. ....			<b>6883</b>
Drive; Model No. 22-14O501 .....	111435		<b>A90</b>
Trans.; Model No. 72060 .....	111435		<b>A90</b>
<b>244-H</b>			
Drive; Model No. 22-14OE01 .....	114860		<b>6714BR</b>



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>246-H</b> Drive; Model No. 42-16BE01, R2-16BE01 ..... 114860 Trans.; Model No. 72081, 72101 ..... 114860			6714BR 6714BR
<b>264-6</b> Trans.; Model No. 72042, 72062 ..... 926719			6898
<b>264-H</b> Trans.; Model No. 72043, 72063 ..... 926718			6463BR
<b>265-6</b> Trans.; Model No. 72045; Ser. No. 69000001-69999999 ..... 926719 Trans.; Model No. 72045; Ser. No. 79000001-89999999 ..... 926955 Trans.; Model No. 72047 ..... 926955			6898 6897 6897
<b>265-H</b> Trans.; Model No. 72046, 72064; Ser. No. 69000001-69999999 ..... 926718 Trans.; Model No. 72046, 72064; Ser. No. 79000001-89999999 ..... 926954 Trans.; Model No. 72048, 72070 ..... 926954			6463BR 6459BR 6459BR
<b>266-H</b> Trans.; Model No. 72083, 72084 ..... 926718			6463BR
<b>267</b> Trans.; W/17 H.P. Eng. .... 944399			6974
<b>267-H</b> Trans.; Model No. 72085; Ser. No. 49000001-69999999 ..... 926718 Trans.; Model No. 72085; Ser. No. 79000001-89999999 ..... 926954 Trans.; Model No. 72104; Ser. No. 69000001-69999999 ..... 926718 Trans.; Model No. 72104; Ser. No. 79000001-89999999 ..... 926954			6463BR 6459BR 6463BR 6459BR
<b>268-H</b> Trans.; Model No. 72086, 72105; Ser. No. 99000001-99999999 ..... 926954 Trans.; Model No. 72103; Ser. No. 49000001-59999999 ..... 926718			6459BR 6463BR
<b>269</b> Trans.; W/19 H.P. Eng. .... 944399			6974
<b>269-H</b> Trans.; Model No. 72102; Ser. No. 69000001-69999999 ..... 926718 Trans.; Model No. 72102; Ser. No. 79000001-89999999 ..... 926954			6463BR 6459BR
<b>270-H</b> Trans.; Model No. 72106, 72110, 72115 ..... 926954			6459BR
<b>310-8</b> Drive; Model No. 31-10K801 ..... 7473 Drive; Model No. 31-10K802, 31-10K803 ..... 787100 Trans.; Model No. 73320 ..... 7473 Trans.; W/10 H.P., 8-Speed Eng. .... 1473			6982 6982 6982 6832
<b>312-8</b> Cross Drive; W/8 H.P., 8-Speed Eng. .... 6738 Deck; W/8 H.P., 8-Speed Eng. .... 102742 Drive; Model No. 31-12K801 ..... 7473 Drive; Model No. 73362, 73380, 73400 ..... 7473 Drive; Model No. 73363, 73428, 73429 ..... 939808 Drive; Model No. R1-12K804, 31-12K802, 31-12K804 ..... 787100 Trans.; W/8 H.P., 8-Speed Eng. .... 7473			6886 6378 6982 6982 6982 6982 6982
<b>312-H</b> Drive; Model No. 31-10K801 ..... 7473 Drive; Model No. 31-10K802, 31-10K803, 51-12KE01, 51-12KE02 ..... 108501			6982 6982
<b>312-H Hydro</b> Cross Drive; W/12 H.P. Eng. .... 6738 Deck; W/12 H.P. Eng. .... 102742 Trans.; W/12 H.P. Eng. .... 7473			6886 6378 6982

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>314-8</b> Drive; Model No. 73400 ..... 7473 Drive; Model No. 73402, 73448, 73449 ..... 939808			6982 6982
<b>314-H</b> Drive; Model No. 73401; Ser. No. 39000001-49999999 ..... 108501 Drive; Model No. 73401; Ser. No. 59000001-59000260 ..... Drive; Model No. 73401; Ser. No. 59000261-69999999 ..... 108501 Drive; Model No. 73403 ..... 108501			6982 6983 6982 6982
<b>316-8</b> Drive; Model No. 73422, 73441 ..... 939809 Drive; Model No. R1-16O804 .....			6983 6983
<b>328-D</b> Eng. .... 98-9676 Eng. To Deck ..... 106-4383 Fan ..... 105-3693		7375	6539BR 6697BR
<b>416-8</b> Cross Drive; W/16 H.P. Eng. .... 1594 Deck; W/16 H.P. Eng. .... 102742 Drive; Model No. 31-16O802, 31-16O803, 31-16O804, 73420, 73440 ..... Trans.; W/16 H.P. Eng. .... 114895			6781BR 6378 6983 6983
<b>416-H</b> Drive; Model No. 41-16OE01, 51-16OE01, 51-16OE02, 73421, 73423 ..... 114895			6983
<b>416-H Hydro</b> Cross Drive; W/16 H.P. Eng. .... 1594 Deck; W/16 H.P. Eng. .... 102742 Snow Thrower Attachment; W/16 H.P. Eng. .... 116332 Trans.; W/16 H.P. Eng. .... 114895			6781BR 6378 6965 6983
<b>520-8</b> Drive; Model No. 41-20O801 ..... 114895			6983
<b>520-H</b> Cross Drive; W/20 H.P. Eng. .... 1594 Deck; W/20 H.P. Eng. .... 102742 Drive; Model No. 41-20OE01, 41-20OE02, 41-20OE073501, 73502, 73520, 73521, R1-20OE02 ..... 114895 Trans.; W/20 H.P. Eng. .... 114895			6781BR 6378 6983 6983
<b>520-LXI</b> Fan; Model No. 73545, 73546, 73547, 73580 ..... 959784		7325	
<b>523-DXI</b> Fan; Model No. 73550, 73551, 73552, 73590 ..... 99-9156		7370	
<b>612-Z</b> Cross Drive ..... 116667 Drive; Model No. Y1-12OE02 ..... 116527 Eng. To J.S. .... 116183 J.S. To Deck ..... 116666 P.T.O.; Model No. Y1-12OE02 ..... 116183 Trans.; W/12.5 H.P. Eng. .... 116527			6885 6843 6951 6977 6951 6843
<b>616-Z</b> Drive; Model No. Y1-16OEE4, Y1-16OE01, Y1-16OE02, Y1-16OE03, Y1-16OE04, 74021, 74041, 74120 ..... 116527 Eng. To J.S. .... 116183 P.T.O.; Model No. Y1-16OEE4, Y1-16OE01, Y1-16OE02, Y1-16OE03, Y1-16OE04, 74021, 74041, 74120 ..... 116183			6843 6951 6951
<b>620-Z</b> Drive; Model No. Y1-20OE02, Y1-20OE03, 74101 ..... 116527 P.T.O.; Model No. Y1-20OE02, Y1-20OE03, 74101 ..... 116183			6843 6951
<b>620-ZI</b> Eng. To J.S. .... 116183			6951



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>724-Z</b>			
P.T.O. ....	448990		6538BR
<b>1142</b>			
Deck .....	362920		6861
Mower .....	362930		6378
Trans. ....	282650		A100
<b>1144 (57354, 57358)</b>			
Deck; Ser. No. 700001 & After .....			6843
Traction; Ser. No. 700001 & After .....	282650		A100
<b>02000</b>			
Clutch .....	98-5311		7087BR
Countershaft .....	98-5314		7088BR
Reel Drive .....	98-5310		6528BR
Traction .....	98-5309		6774BR
<b>2000-D</b>			
Fan .....	99-8153	7365	
<b>02001; 02002</b>			
Clutch .....	98-5311		7087BR
Countershaft .....	98-5314		7088BR
Reel Drive .....	98-5310		6528BR
Traction .....	98-5309		6774BR
<b>02003</b>			
Countershaft .....	98-5314		7088BR
Reel Drive .....	98-5310		6528BR
<b>03100</b>			
Gen.; Ser. No. 50001 & After .....	68428		6727
Gen.; Ser. No. 60001 & After .....	68428		6727
<b>3100-D</b>			
Alt.; 2013 & Older .....	99-3467	7370	
Alt.; 2014 & Newer .....	130-1241	7345	
Pump Drive .....	95-8730		7123BR
<b>03102</b>			
Gen.; Ser. No. 80001 & After .....	68428		6727
<b>03104</b>			
Gen.; Ser. No. 50001 & After .....	68428		6727
Gen.; Ser. No. 60001 & After .....	68428		6727
<b>03112</b>			
Gen.; Ser. No. 800001 & After .....	68428		6727
<b>03115</b>			
Gen. ....	68428		6727
<b>3250D</b>			
Alt. ....	119-4486	7345	
<b>3280-D</b>			
Eng. To Deck .....	63-6240		6808BR
<b>3320 Groundsmaster</b>			
Fan & W.P. ....	99-9156	7370	
P.T.O. ....	63-6240		6808BR
<b>3400; 3420</b>			
Alt. ....	119-4486	7345	
<b>3500-D</b>			
Alt. ....	98-9676	7375	
Hydro. Drive .....	99-3619		6903BR
<b>3550-D</b>			
Pump .....	99-3619		6903BR
<b>4000-D (30448)</b>			
Alt. ....	115-8599	9412	9412HD
Blade Drive .....	108-8076		④7101BR
<b>4000-D (30609)</b>			
Blade Drive .....	108-8076		④7101BR
W.P. ....	127-2998	9395	9395HD
<b>4000-D</b>			
Alt. ....	98-7705	9425	9425HD
<b>4010-D (30446)</b>			
Alt. & Compr. ....	117-5674	9440	9440HD
Blade Drive .....	108-8076		④7101BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>4010-D (30607)</b>			
Blade Drive .....	108-8076		④7101BR
W.P. ....	127-2998	9395	9395HD
<b>4100-D (30449)</b>			
Alt. ....	115-8599	9412	9412HD
Blade Drive .....	108-8077		6855BR
<b>4100-D (30608)</b>			
Blade Drive .....	108-8077		6855BR
W.P. ....	127-2998	9395	9395HD
<b>4110-D (30447)</b>			
Alt. & Compr. ....	117-5674	9440	9440HD
Blade Drive .....	108-8077		6855BR
<b>4110-D (30606)</b>			
Blade Drive .....	108-8077		6855BR
W.P. ....	127-2998	9395	9395HD
<b>4300-D (30859)</b>			
Alt. ....	98-9676	7375	
<b>4300-D (30864)</b>			
W.P. ....	127-2998	9395	9395HD
<b>4500-D (30857)</b>			
Alt. ....	115-8599	9412	9412HD
<b>4500-D (30881)</b>			
W.P. ....	127-2998	9395	9395HD
<b>4700-D (30858)</b>			
Alt. ....	115-8599	9412	9412HD
<b>4700-D (30882)</b>			
W.P. ....	127-2998	9395	9395HD
<b>5100-D</b>			
Alt. & W.P. ....	67-4410		6735
<b>5200-D; 5210; 5400-D; 5410</b>			
Alt. ....	98-9676	7375	
<b>5410-D</b>			
W.P. ....	127-2998	9395	9395HD
<b>5500-D</b>			
Alt. ....	98-9676	7375	
Fan .....	98-3921		6895BR
<b>5510</b>			
Alt. ....	98-9676	7375	
<b>5510-D</b>			
W.P. ....	127-2998	9395	9395HD
<b>5610</b>			
Alt. ....	98-9676	7375	
<b>5900 (31598); 5910 (31599)</b>			
Blade Drive .....	112-7377		⑥6502BR
Compr. ....	105-3693		6697BR
Deck Drive .....	112-7376		6845BR
W.P. ....	117-5420		TR24500
<b>7000-D</b>			
W.P. ....	127-2998	9395	9395HD
<b>7200</b>			
Blade - Left; W/60" Side Discharge			
Deck .....	105-0887		7072BR
Blade - Left; W/72" Rear Discharge			
Deck .....	110-9592		6856BR
Blade - Left; W/72" Side Discharge			
Deck .....	110-9590		6949BR
Blade - Right; W/72" Rear Discharge			
Deck .....	110-9593		6555BR
Blade - Right; W/72" Side Discharge			
Deck .....	110-9591		6644BR
Fan .....	98-9676	7375	
<b>30185 Pro Line Auto Steer</b>			
Recycler To Trans.; W/14 H.P., 4-Speed Eng.; W/48" Blade .....	269670		6840

④Four Required ⑥Six Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>30190 Pro Line 118</b>			
Recycler To Trans.; W/18 H.P. Eng.;			
W/48" Blade .....	541390		6755BR
<b>30401; 30402; 30450; 30455</b>			
Deck - Left & Right .....	861960		6626BR
<b>30580</b>			
Deck - Center .....	938457		6696BR
Deck - Left & Right .....	99-2318		6865BR
W.P. ....	70-3450	9520	9520HD
<b>30581; 30592</b>			
Deck - Center .....	938457		6696BR
Deck - Left & Right .....	99-2318		6865BR
Fan .....	98-9008		6698BR
W.P. ....	99-2159	9463	9463HD
<b>51013; 51053</b>			
Deck .....	31560	2500	6850
Traction .....	35585	2430	6843
<b>51060; 51070</b>			
Blade .....	35843		6845
Drive; W/43" Belt O.C. ....	36348		6843
Drive; W/47" Belt O.C. ....	34577		6847
<b>52125 (7-25)</b>			
Deck .....	262770		6850
<b>55000; 55001</b>			
Blade .....			3V670
Blade - Right .....	70946		6830
Trans. ....	70824		6831
<b>55002; 55003; 55050; 55051; 55055</b>			
Deck .....	74228		6848
P.T.O. ....	74231		6833
Traction .....	74232		6871
<b>55100; 55101</b>			
Blade .....			3V670
Blade - Right .....	70946		6830
Trans. ....	70824		6831
<b>55150; 55152</b>			
Deck .....	74228		6848
P.T.O. ....	74231		6833
Traction .....	74233		6860
<b>55166</b>			
Deck; W/36" Deck .....	79160		6857
Deck; W/48" Belt O.C. ....	74228		6848
Eng. To J.S.; W/36" Deck .....	74231		6833
P.T.O. ....	74231		6833
Spindle; W/36" Deck .....	74228		6848
Spindle; W/57" Belt O.C. ....	79160		6857
Starter/Gen.; W/36" Deck .....	70657	7320	
Traction .....	74232		6871
Trans.; W/36" Deck .....	74232		6871
<b>55200</b>			
Belt; W/34" Belt O.C. ....	70073		6834
Drive .....	70550		6727
Starter/Gen. ....	70530		6735
Trans. ....	70551		3V375
<b>55233</b>			
Deck .....	74228		6848
P.T.O. ....	74231		6833
Spindle .....	79160		6857
Starter/Gen. ....	70657	7320	
Traction .....	74232		6871
<b>55256</b>			
Deck .....	74228		6848
P.T.O. ....	74231		6833
Spindle .....	79160		6857
Traction .....	74233		6860
Trans. ....	79390		6860
<b>55275</b>			
Mower Deck .....	74228		6848
P.T.O. ....	74231		6833
Spindle .....	79160		6857

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>55275 - Continued</b>			
Trans. ....	79390		6860
<b>55300</b>			
Belt; W/34" Belt O.C. ....	70073		6834
Drive .....	70550		6727
Starter/Gen. ....	70530		6735
Trans. ....	70551		3V375
<b>55301; 55302</b>			
Blade .....	70073		6834
Deck .....	70354		6833
Drive .....	70550		6727
Gen. ....	70530		6735
Trans.; W/34" Belt O.C. ....	70073		6834
Trans.; W/37 1/2" Belt O.C. ....	70551		3V375
Trans.; W/75" Belt O.C. ....	70630		3V750
<b>55400</b>			
Belt; W/34" Belt O.C. ....	70073		6834
Drive .....	70550		6727
Starter/Gen. ....	70530		6735
Trans. ....	70551		3V375
<b>55401; 55402</b>			
Blade .....	70073		6834
Deck .....	70354		6833
Drive .....	70550		6727
Gen. ....	70530		6735
Trans.; W/34" Belt O.C. ....	70073		6834
Trans.; W/37 1/2" Belt O.C. ....	70551		3V375
Trans.; W/75" Belt O.C. ....	70630		3V750
<b>56000</b>			
Eng. To Deck .....	111710		6853
Trans. ....	111730		6835
<b>56002; 56004</b>			
Blade .....	262770		6850
Trans. ....	192650		6376
<b>56005</b>			
Eng. To Deck .....	126550		6854
Trans. ....	111730		6835
<b>56006</b>			
Blade .....	262770		6850
Trans. ....	192650		6376
<b>56010</b>			
Eng. To Deck .....	126550		6854
Trans. ....	111730		6835
<b>56015</b>			
Deck .....	192220		6844
Traction .....	126220		6833
<b>56020; 56022; 56025; 56027</b>			
Deck .....	188890		6845
Trans. ....	192650		6376
<b>56030</b>			
Blade .....	188890		6845
<b>56033</b>			
Deck .....	188890		6845
Trans. ....	192650		6376
<b>56036; 56044</b>			
Blade .....	262770		6850
Trans. ....	192650		6376
<b>56100</b>			
Blade .....	111720		6853
Deck .....	111740		6860
Trans. ....	111730		6835
<b>56108</b>			
Blade .....	126430		6846
Deck; W/7 H.P. Eng. ....	126420		6841
Trans. ....	196960		6835
<b>56125</b>			
Blade .....	262770		6850
Trans. ....	192650		6376

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>56138</b>			
Traction .....	471410		6224
<b>56145</b>			
Blade .....	471420	6559BR	
Traction .....	471410	6224	
<b>56150</b>			
Blade .....	471420	6559BR	
Deck .....	111740	6860	
Trans. ....	111730	6835	
<b>56155</b>			
Blade .....	471420	6559BR	
Traction .....	471410	6224	
<b>56170</b>			
Blade .....	471420	6559BR	
<b>56173</b>			
Blade .....	126430	6846	
Deck; W/7 H.P. Eng. ....	126420	6841	
Trans. ....	196960	6835	
<b>56175; 56176; 56177</b>			
Blade .....	471420	6559BR	
<b>56180</b>			
Blade .....	126430	6846	
Deck; W/7 H.P. Eng. ....	126420	6841	
Trans. ....	196960	6835	
<b>56185; 56190; 56195</b>			
Blade .....	471420	6559BR	
<b>56500</b>			
Deck .....	128260	A43	
<b>56525; 56575</b>			
Deck .....	128260	A43	
Traction .....	126220	6833	
<b>57000</b>			
Belt; W/31" Belt O.C.; W/4 H.P. Eng. ....	70824	6831	
Belt; W/35" Belt O.C.; W/4 H.P. Eng. ....	70737	6835	
Trans. ....	70737	6835	
<b>57001</b>			
Belt; W/31" Belt O.C.; W/5 H.P. Eng. ....	70824	6831	
Belt; W/35" Belt O.C.; W/5 H.P. Eng. ....	70737	6835	
Trans. ....	70737	6835	
<b>57002</b>			
Drive .....	73887	6829	
P.T.O. ....	73887	6829	
Trans. ....	73890	6845	
<b>57003</b>			
Drive .....	73887	6829	
Trans.; W/29" Belt O.C. ....	73887	6829	
Trans.; W/45" Belt O.C. ....	73888	6845	
<b>57017</b>			
Drive .....	73887	6829	
P.T.O. ....	73887	6829	
Trans. ....	73890	6845	
<b>57025</b>			
Drive .....	73887	6829	
Trans.; W/29" Belt O.C. ....	73887	6829	
Trans.; W/45" Belt O.C. ....	73888	6845	
<b>57043</b>			
Drive .....	73887	6829	
P.T.O. ....	73887	6829	
Trans. ....	73890	6845	
<b>57050</b>			
Belt; W/31" Belt O.C.; W/5 H.P. Eng. ....	70824	6831	
Belt; W/35" Belt O.C.; W/5 H.P. Eng. ....	70737	6835	
Trans. ....	70827	6831	
<b>57051; 57054; 57060; 57077</b>			
Drive .....	73887	6829	
P.T.O. ....	73887	6829	
Trans. ....	73890	6845	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>57100</b>			
Blade .....	70162		6932
Trans. ....	70161		6860
<b>57101</b>			
Blade .....	70162		6932
Trans. ....	73476		6862
<b>57102</b>			
Blade .....	36348		6843
P.T.O. ....	73887		6829
Spindle .....	73975		6850
Trans. ....	73890		6845
<b>57104</b>			
Deck .....	36348		6843
P.T.O. ....	73887		6829
Spindle .....	73975		6850
Trans. ....	73890		6845
<b>57111</b>			
Blade; W/43" Belt O.C. ....	76740		6843
Blade; W/50" Belt O.C. ....	73975		6850
Eng. ....	73887		6829
Trans. ....	73890		6845
<b>57131</b>			
Blade; W/43" Belt O.C. ....	124790		6843
Blade; W/47" Belt O.C. ....	124780		6847
P.T.O. ....	73887		6829
Trans. ....	73890		6845
<b>57200</b>			
Blade .....	70162		6932
Trans. ....	70161		6860
<b>57201</b>			
Blade .....	70162		6932
Trans. ....	73476		6862
<b>57202</b>			
Blade .....	36348		6843
P.T.O. ....	73887		6829
Spindle .....	73975		6850
Trans. ....	73890		6845
<b>57204</b>			
Deck .....	36348		6843
P.T.O. ....	73887		6829
Spindle .....	73975		6850
Trans. ....	73890		6845
<b>57222</b>			
Blade; W/43" Belt O.C. ....	76740		6843
Blade; W/50" Belt O.C. ....	73975		6850
Eng. ....	73887		6829
Trans. ....	73890		6845
<b>57228</b>			
Blade; W/43" Belt O.C. ....	124790		6843
Blade; W/47" Belt O.C. ....	124780		6847
Drive .....	73887		6829
P.T.O. ....	73887		6829
Trans. ....	73890		6845
<b>57241</b>			
Blade; W/43" Belt O.C. ....	124790		6843
Blade; W/47" Belt O.C. ....	124780		6847
Drive .....	73887		6829
P.T.O. ....	73887		6829
Trans. ....	73890		6845
<b>57300; 57305; 57351</b>			
Blade .....	285250		6853
Trans. ....	282650		A100
<b>57354/1144</b>			
Blade; Ser. No. 6000001 & After .....	576990		6882
Trans.; Ser. No. 6000001 & After .....	282650		A100
<b>57356</b>			
Deck .....	362920		6861
Trans. ....	282650		A100
<b>57358/1444</b>			
Trans.; Ser. No. 6000001 & After .....	282650		A100



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>57359/1142</b> Trans.; Ser. No. 10000001 & After .....	282650		A100
<b>57360</b> Deck .....	285250	6853	
Traction .....	282650	A100	
<b>57365/1138</b> Trans.; Ser. No. 60000001 & After .....	282650		A100
<b>57375; 57380; 57385; 57400; 57410; 57420</b> Deck .....	285250	6853	
Traction .....	282650	A100	
<b>59147</b> Deck .....	574750	6858	
<b>59176; 59178</b> Blade .....	471420	6559BR	
<b>70040</b> Blade .....	671390	6583BR	
<b>70041; 70044; 70060; 70122</b> Deck .....	980710	6583BR	
Traction .....	670900	6840	
<b>74141</b> Deck Drive .....	119-9926	6720BR	
Hydro. Drive .....	114860	6714BR	
<b>74143</b> Deck Drive .....	114-5857	6902BR	
Hydro. Drive .....	114860	6714BR	
<b>74145</b> Deck Drive .....	114-5858	6881BR	
Hydro. Drive .....	114860	6714BR	
<b>74162; 74199; 74203; 74209; 74212</b> Deck .....	446260	6409BR	
Eng. To Deck; W/62" Deck .....	994647	6599BR	
Hydro. ....	1-633749	6666BR	
<b>74213</b> Deck .....	446260	6409BR	
Eng. To Deck; W/62" Deck .....	994647	6599BR	
Hydro. ....	1-633749	6666BR	
<b>74216; 74218; 74225; 74226; 74231; 74234; 74236</b> Deck .....	446260	6409BR	
Eng. To Deck; W/62" Deck .....	994647	6599BR	
Hydro. ....	1-633749	6666BR	
<b>74237</b> Eng. To Deck; W/52", 72" Deck .....	105-7790	6693BR	
<b>74239</b> Eng. To Deck; W/52" Deck .....	105-7790	6693BR	
<b>74240</b> Deck .....	446260	6409BR	
Eng. To Deck; W/62" Deck .....	994647	6599BR	
Hydro. ....	1-633749	6666BR	
<b>74242</b> Eng. To Deck; W/52" Deck .....	105-7790	6693BR	
Hydro. ....	1-633749	6666BR	
<b>74243</b> Eng. To Deck; W/52" Deck .....	105-7790	6693BR	
<b>74244</b> Deck Drive; W/60" Deck .....	105-8783	6659BR	
<b>74248</b> Eng. To Deck; W/52" Deck .....	105-7790	6693BR	
<b>74249</b> Deck Drive; W/60" Deck .....	105-8783	6659BR	
Hydro. ....	1-633749	6666BR	
<b>74252</b> Deck Drive; W/72" Deck .....	106-7350	7059BR	
<b>74253</b> Deck Drive; W/60" Deck .....	114-4420	6883BR	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>74254</b> Eng. To Deck; W/72" Deck .....	105-7790		6693BR
<b>74258</b> Deck .....	446260		6409BR
Eng. To Deck; W/62" Deck .....	994647		6599BR
Hydro. ....	1-633749		6666BR
<b>74261</b> Eng. To Deck; W/52" Deck .....	105-7790		6693BR
<b>74266</b> Deck Drive; W/52" Deck .....	108-5951		6970BR
Fan; 2012 & Older .....	112-8353	7350	
Fan; 2013 & Newer .....	110-3796	7335	
Gear Box .....	110-3866		7122BR
Hydro. ....	110-3865		6700BR
<b>74267</b> Deck Drive; W/60" Deck .....	114-4420		6883BR
Fan; 2012 & Older .....	112-8353	7350	
Fan; 2013 & Newer .....	110-3796	7335	
Gear Box .....	110-3866		7122BR
Hydro. ....	110-3865		6700BR
<b>74268</b> Eng. To Deck .....	107-7738		6662BR
W.P. ....	99-9156	7370	
<b>74268TE</b> Deck .....	446260		6409BR
Eng. To Deck; W/62" Deck .....	994647		6599BR
Hydro. ....	1-633749		6666BR
<b>74269</b> Eng. To Deck .....	107-7738		6662BR
W.P. ....	99-9156	7370	
<b>74271</b> Eng. To Deck; W/52" Deck .....	105-7790		6693BR
<b>74272</b> Deck Drive; W/60" Deck .....	105-8783		6659BR
<b>74273</b> Deck Drive; W/72" Deck .....	106-7350		7059BR
<b>74274</b> Eng. To Deck; W/72" Deck .....	105-7790		6693BR
Fan; 2012 & Older .....	112-8353	7350	
Fan; 2013 & Newer .....	110-3796	7335	
Gear Box .....	110-3866		7122BR
Hydro. ....	110-3865		6700BR
<b>74282</b> Eng. To Deck; W/52" Deck .....	105-7790		6693BR
<b>74283</b> Deck Drive; W/60" Deck .....	105-8783		6659BR
<b>74284</b> Deck Drive; W/72" Deck .....	106-7350		7059BR
<b>74291</b> Eng. To Deck; W/52" Deck .....	105-7790		6693BR
<b>74292</b> Deck Drive; W/60" Deck .....	105-8783		6659BR
<b>74295</b> Deck Drive .....	105-7790		6693BR
<b>74296</b> Deck Drive .....	105-8783		6659BR
<b>74297</b> Deck Drive .....	106-7350		7059BR
<b>74310; 74311; 74312</b> Deck Drive .....	130-2870		6925BR
Hydro. Drive .....	130-2871		6930BR
<b>74409</b> Deck Drive .....	114-0453		6686BR
<b>74410; 74412; 74416</b> Deck Drive .....	106-7369		6661BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
74417 Deck Drive .....	114-8154		6802BR
74418 Deck Drive .....	106-7369		6661BR
74444 Deck Drive .....	114-8154		6802BR
74445 Deck Drive .....	106-7369		6661BR
74448 Deck Drive; 2008 & Older .....	106-7369		6661BR
Deck Drive; 2009 & Newer .....	114-8154		6802BR
74449 Deck Drive .....	106-7369		6661BR
74504 Deck Drive .....	131-1121		7112BR
Hydro. Drive .....	131-1124		6886BR
74505 Deck Drive .....	131-1122		7113BR
Hydro. Drive .....	131-1124		6886BR
74513 Deck Drive .....	131-1123		6885BR
Hydro. Drive .....	131-1124		6886BR
74518 Deck Drive .....	131-1121		7112BR
Hydro. Drive .....	131-1124		6886BR
74519 Deck Drive .....	131-1122		7113BR
Hydro. Drive .....	131-1124		6886BR
74534 Deck Drive .....	117-7641		6424BR
Hydro. Drive .....	119-0174		6922BR
74536 Blade Drive .....	117-7649		7036BR
Eng. To Deck .....	117-7648		6871BR
Hydro. Drive .....	119-0174		6922BR
74538 Deck Drive .....	114-0453		6686BR
Hydro. Drive .....	114567		6927BR
74539 Deck Drive .....	114-0454		6875BR
Hydro. Drive .....	114567		6927BR
74548 Deck Drive .....	114-0453		6686BR
Hydro. Drive .....	114567		6927BR
74549 Deck Drive .....	114-0454		6875BR
Hydro. Drive .....	114567		6927BR
74553 Deck Drive .....	117-9607		7039BR
Hydro. Drive .....	114567		6927BR
74558 Deck Drive .....	114-0453		6686BR
Hydro. Drive .....	114567		6927BR
74559 Deck Drive .....	114-0454		6875BR
Hydro. Drive .....	114567		6927BR
74568 Deck Drive .....	114-0453		6686BR
Hydro. Drive .....	114567		6927BR
74569 Deck Drive .....	114-0454		6875BR
Hydro. Drive .....	114567		6927BR
74574 Deck Drive .....	114-0453		6686BR
Hydro. Drive .....	114567		6927BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
74575 Deck Drive .....	114-0454		6875BR
Hydro. Drive .....	114567		6927BR
74576; 74583 Deck Drive .....	106-7369		6661BR
Hydro. Drive .....	114567		6927BR
74588 Deck Drive .....	114-0453		6686BR
Hydro. Drive .....	114567		6927BR
74589 Deck Drive .....	114-0454		6875BR
Hydro. Drive .....	114567		6927BR
74620 Deck Drive; W/32" Deck .....	119-8821		6551BR
Hydro. Drive .....	119-3309		6887BR
74621 Deck Drive .....	119-8821		6551BR
Hydro. Drive .....	119-3309		6887BR
74622; 74623; 74624; 74626; 74627 Deck Drive; W/42" Deck .....	119-8819		6872BR
Hydro. Drive .....	119-3309		6887BR
74630; 74632 Deck Drive; W/50" Deck .....	119-8820		6873BR
Hydro. Drive .....	119-3321		6888BR
74640 Deck Drive; W/42" Deck .....	119-8819		6872BR
Hydro. Drive .....	119-3309		6887BR
74641 Deck Drive; W/50" Deck .....	119-8820		6873BR
Hydro. Drive .....	119-3321		6888BR
74701; 74702 Deck .....	993904		6598BR
74710 Deck Drive .....	119-8821		6551BR
74720; 74721; 74723 Deck Drive .....	119-8819		6872BR
74730; 74731 Deck Drive .....	119-8820		6873BR
74740 Deck Drive .....	130-0843		7016BR
74750 Deck Drive .....	130-0842		6810BR
74760 Deck Drive .....	119-8819		6872BR
74770 Deck Drive .....	119-8820		6873BR
74780; 74781 Deck Drive .....	119-8821		6551BR
74784; 74785; 74787 Deck Drive .....	119-8819		6872BR
74790; 74797; 74798 Deck Drive .....	119-8820		6873BR
74840 Hydro. Drive .....	115-9613		6780BR
74841 Deck Drive; W/48" Deck .....	117-7325		6859BR
Hydro. Drive .....	115-9613		6780BR
74842 Deck Drive; W/54" Deck .....	115-4971		6661BR
Hydro. Drive .....	115-9613		6780BR
74843 Deck Drive; W/60" Deck .....	115-4972		6880BR
Hydro. Drive .....	115-9613		6780BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>74851</b>			
Deck Drive .....	117-7325		6859BR
Hydro. Drive .....	115-9613		6780BR
<b>74852</b>			
Deck Drive .....	115-4971		6661BR
Hydro. Drive .....	115-9613		6780BR
<b>74853</b>			
Deck Drive .....	115-4972		6880BR
Hydro. Drive .....	115-9613		6780BR
<b>74855; 74861</b>			
Deck Drive .....	117-7325		6859BR
Hydro. Drive .....	115-9613		6780BR
<b>74862</b>			
Deck Drive .....	115-4971		6661BR
Hydro. Drive .....	115-9613		6780BR
<b>74863</b>			
Deck Drive .....	115-4972		6880BR
Hydro. Drive .....	115-9613		6780BR
<b>74871</b>			
Deck Drive; W/48" Deck .....	117-7325		6859BR
Hydro. Drive .....	115-9613		6780BR
<b>74872</b>			
Deck Drive; W/54" Deck .....	115-4971		6661BR
Hydro. Drive .....	115-9613		6780BR
<b>74882</b>			
Deck Drive .....	115-4971		6661BR
Hydro. Drive .....	115-9613		6780BR
<b>74883</b>			
Deck Drive .....	115-4972		6880BR
Hydro. Drive .....	115-9613		6780BR
<b>74891</b>			
Deck Drive .....	117-7325		6859BR
Hydro. Drive .....	115-9613		6780BR
<b>74892</b>			
Deck Drive .....	115-4971		6661BR
Hydro. Drive .....	115-9613		6780BR
<b>74893</b>			
Deck Drive .....	115-4972		6880BR
Hydro. Drive .....	115-9613		6780BR
<b>74901</b>			
Deck Drive .....	115-7407		6885BR
Hydro.; 2009 & Older .....	109-8069		6780BR
Hydro.; 2010 & Newer .....	109-3388		6780BR
<b>74903</b>			
Deck Drive .....	115-7426		6761BR
Hydro.; 2009 & Older .....	109-8069		6780BR
Hydro.; 2010 & Newer .....	109-3388		6780BR
<b>74904</b>			
Deck Drive .....	115-7407		6885BR
Hydro. Drive .....	109-3388		6780BR
<b>74906</b>			
Deck Drive .....	115-7426		6761BR
Hydro. Drive .....	109-3388		6780BR
<b>74915</b>			
Deck Drive .....	114-5858		6881BR
Hydro.; 2009 & Older .....	109-8069		6780BR
Hydro.; 2010 & Newer .....	109-3388		6780BR
<b>74916; 74918</b>			
Deck Drive .....	114-5859		6884BR
Hydro. Drive .....	109-3388		6780BR
<b>74921</b>			
Deck Drive .....	115-7407		6885BR
Hydro. Drive .....	109-8069		6780BR
<b>74922</b>			
Deck Drive .....	115-7407		6885BR
Hydro. Drive .....	109-3388		6780BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>74923</b>			
Deck Drive .....	115-7426		6761BR
Hydro.; 2009 & Older .....	109-8069		6780BR
Hydro.; 2010 & Newer .....	109-3388		6780BR
<b>74925</b>			
Deck Drive .....	114-5858		6881BR
Hydro.; 2009 & Older .....	109-8069		6780BR
Hydro.; 2010 & Newer .....	109-3388		6780BR
<b>74926</b>			
Deck Drive .....	114-5858		6881BR
Hydro. Drive .....	109-3388		6780BR
<b>74927</b>			
Deck Drive .....	114-5859		6884BR
Hydro.; 2009 & Older .....	109-8069		6780BR
Hydro.; 2010 & Newer .....	109-3388		6780BR
<b>74928</b>			
Deck Drive .....	114-5859		6884BR
Hydro. Drive .....	109-3388		6780BR
<b>74930; 74933</b>			
Deck Drive .....	114-5858		6881BR
Hydro. Drive .....	109-3388		6780BR
<b>74934</b>			
Deck Drive .....	114-5859		6884BR
Hydro. Drive .....	109-3388		6780BR
<b>74935</b>			
Deck Drive .....	114-5858		6881BR
Hydro.; 2009 .....	109-8069		6780BR
Hydro.; 2010 .....	109-3388		6780BR
<b>74936</b>			
Deck Drive .....	114-5858		6881BR
Hydro. Drive .....	109-3388		6780BR
<b>74937</b>			
Deck Drive .....	114-5859		6884BR
Hydro.; 2009 .....	109-8069		6780BR
Hydro.; 2010 .....	109-3388		6780BR
<b>74938</b>			
Deck Drive .....	114-5859		6884BR
Hydro. Drive .....	109-3388		6780BR
<b>74942</b>			
Blade Drive .....	116-8187		7060BR
Eng. To Deck .....	125-9371		7058BR
Hydro. Drive .....	109-3388		6780BR
<b>74944</b>			
Blade Drive .....	116-8501		7061BR
Eng. To Deck .....	109-8070		6879BR
Hydro. Drive .....	109-3388		6780BR
<b>74946</b>			
Deck Drive .....	114-5858		6881BR
Hydro. Drive .....	109-3388		6780BR
<b>74947</b>			
Deck Drive .....	114-5859		6884BR
Hydro. Drive .....	109-3388		6780BR
<b>74951; 74952</b>			
Deck Drive .....	115-7407		6885BR
Hydro. Drive .....	116-1953		6862BR
<b>74953</b>			
Deck Drive .....	115-7426		6761BR
Hydro. Drive .....	116-1953		6862BR
<b>74954</b>			
Deck Drive .....	114-5858		6881BR
Hydro. Drive .....	116-1953		6862BR
<b>74955</b>			
Deck Drive .....	115-7426		6761BR
Hydro. Drive .....	116-1953		6862BR
<b>74957; 74958</b>			
Deck Drive .....	114-5858		6881BR
Hydro. Drive .....	109-3388		6780BR

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>74959</b>			
Deck Drive .....	114-5859		6884BR
Hydro. Drive .....	109-3388		6780BR
<b>74975</b>			
Deck Drive .....	114-5858		6881BR
Hydro. Drive .....	109-3388		6780BR
<b>74977</b>			
Deck Drive .....	114-5859		6884BR
Hydro. Drive .....	109-3388		6780BR
<b>74990; 74991; 74992</b>			
Deck Drive .....	114-5858		6881BR
Hydro. Drive .....	109-3388		6780BR
<b>74993</b>			
Deck Drive .....	114-5859		6884BR
Hydro. Drive .....	109-3388		6780BR
<b>78922</b>			
Deck Drive .....	115-7407		6885BR
Hydro. Drive .....	109-3388		6780BR
<b>78924</b>			
Deck Drive .....	115-7426		6761BR
Hydro. Drive .....	109-3388		6780BR
<b>79558</b>			
Deck Drive .....	114-0453		6686BR
Hydro. Drive .....	114567		6927BR
<b>79559</b>			
Deck Drive .....	114-0454		6875BR
Hydro. Drive .....	114567		6927BR
<b>573571/1142</b>			
Trans.; Ser. No. 50000001 & After .....	282650		A100
<b>Big Red</b>			
Blade; W/37" Belt O.C. ....	27173	2370	
Blade; W/45" Belt O.C. ....	35843		6845
Deck; W/47" Belt O.C. ....	34577		6847
Deck; W/50" Belt O.C. ....	27139		6850
Drive .....	36348		6843
<b>Colt</b>			
Drive; W/25" Deck .....	27166	3240	
<b>GM44</b>			
Eng. To Trans. ....	541390		6755BR
<b>Groundsmaster 3000</b>			
Alt. ....	929785		6733
Deck - Center; W/84" Deck .....	93-4838		6694BR
Deck - Left & Right; W/84" Deck .....	93-4839		②6406BR
Gov. ....	678510		6753
Spindle; W/52" Deck .....	271160		6571BR
Spindle; W/72" Deck .....	938457		6696BR
<b>Groundsmaster 3000-D</b>			
Deck - Center; W/84" Deck .....	93-4838		6694BR
Deck - Left & Right; W/84" Deck .....	93-4839		②6406BR
Spindle; W/52" Deck .....	271160		6571BR
Spindle; W/72" Deck .....	938457		6696BR
<b>GT2100</b>			
Deck Drive .....	112-0332		6778BR
Trans. ....	112-0305		6556BR
V.S. To Trans. ....	112-0301		6606BR
<b>GT2200</b>			
Deck Drive .....	112-0332		6778BR
<b>LX420; LX423; LX425; LX426</b>			
Deck Drive .....	112-5800		6663BR
Trans. ....	112-0305		6556BR
V.S. To Trans. ....	112-0301		6606BR
<b>LX427</b>			
Deck Drive .....	112-5800		6663BR
<b>LX460</b>			
Eng. To Deck .....	112-5834		6713BR
Trans. ....	112-0305		6556BR
V.S. To Trans. ....	112-0301		6606BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>LX465; LX466</b>			
Eng. To Deck .....	112-5834		6713BR
<b>LX500</b>			
Deck Drive .....	112-0332		6778BR
Trans. ....	112-0305		6556BR
V.S. To Trans. ....	112-0301		6606BR
<b>Pony</b>			
Reel Drive; W/27" Deck .....	27150	3330	
Traction; W/27" Deck .....	27138	3290	
<b>Proline 120</b>			
J.S. ....	541380		6874
Traction .....	541390		6755BR
<b>Red Rider</b>			
Blade; W/37" Belt O.C. ....	27173	2370	
Blade; W/45" Belt O.C. ....	35843		6845
Deck .....	27139		6850
Drive .....	36348		6843
<b>Sportman</b>			
Blade Countershaft; W/38" Belt O.C. ....	27182	2380	
Blade Countershaft; W/39" Belt O.C. ....	27181	2390	
Deck .....	31560	2500	
Traction .....	27178	3290	
<b>Toro Pony</b>			
Blade; W/25" Deck .....	32604		6835
Trans.; W/25" Deck .....	32451	2300	
<b>XL320</b>			
Deck Drive .....	88-6260		6851
Traction .....	94-4291		6899
<b>XL380</b>			
Deck Drive .....	88-6250		6627BR
Traction .....	88-6270		6861
<b>XL380H</b>			
Deck Drive .....	88-6250		6627BR
Trans. ....	88-6280		6884
<b>XL440H</b>			
Transaxle .....	88-6250		6627BR
<b>Y1-12OE01; Y1-12OE02; Y1-16OE01;</b>			
<b>Y1-16OE02; Y1-16OE03; Y1-16OE04;</b>			
<b>Y1-20OE02; Y1-20OE03; Z1-24OE01;</b>			
<b>Z1-24OE02</b>			
P.T.O. ....	448990		6538BR
<b>Z1-24OE03; Z1-24OE04; Z1-24OE05</b>			
P.T.O. ....	448990		6538BR
<b>Z252; Z252L</b>			
Hydro. ....	1-633749		6666BR
<b>Z253; Z255; Z256E</b>			
Deck .....	446260		6409BR
Eng. To Deck; W/62" Deck .....	994647		6599BR
Hydro. ....	1-633749		6666BR
<b>Z380; Z420</b>			
Deck Drive .....	106-2173		6923BR
Hydro. Drive .....	106-2174		6660BR
<b>Z480</b>			
Hydro. Drive .....	106-2174		6660BR
<b>Z4200; Z4202; Z4220; Z4235</b>			
Deck Drive .....	110-6871		6928BR
Hydro. Drive .....	110-6774		6793BR
<b>Z4800</b>			
Deck Drive .....	109-5364		6708BR
Hydro. Drive .....	109-3388		6780BR
<b>Z5000; Z5020; Z5030; Z5035; Z5040; Z5060</b>			
Deck Drive .....	110-6892		7054BR
Hydro. Drive .....	110-6774		6793BR
<b>Z5200</b>			
Deck Drive .....	109-3661		6782BR
Hydro. Drive .....	109-3388		6780BR

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>				<b>TRACTOR SUPPLY - Continued</b>			
<b>Z-Master</b>				<b>44-1897</b>			
Deck .....	106-7369		6661BR	Drive .....	16348		6838
Deck Drive; W/60" Deck .....	105-8783		6659BR	Trans. ....			6852
Eng. To Deck; W/52", 72" Deck .....	105-7790		6693BR	<b>44-1926</b>			
Eng. To Deck; W/62" Deck .....	994647		6599BR	P.T.O. ....	7540123		3V335
<b>ZX4800</b>				Trans. ....	7540124		6857
Deck Drive .....	117-7325		6859BR	<b>44-1932; 44-1933; 44-1934</b>			
Hydro. Drive .....	115-9613		6780BR	Gen. ....	7540139	7380	
<b>ZX5000</b>				P.T.O. ....	7540165		6834
Hydro. Drive .....	115-9613		6780BR	Trans. ....	7540124		6857
<b>ZX5400; ZX5450</b>				<b>44-1937</b>			
Deck Drive .....	115-4971		6661BR	Blade .....	7540147	3520	6952
Hydro. Drive .....	115-9613		6780BR	Drive; W/25" Belt O.C. ....	7540135		6925
<b>ZX6030; ZX6050</b>				Drive; W/31" Belt O.C. ....	7540136		6931
Deck Drive .....	115-4972		6880BR	<b>44-1955</b>			
Hydro. Drive .....	115-9613		6780BR	P.T.O. ....	7540123		3V335
<b>TRACTOR SUPPLY</b>				Trans. ....	7540124		6857
<b>44-196</b>				<b>44-1956</b>			
P.T.O. ....	7540165		6834	Gen. ....	7540139	7380	
<b>44-1827</b>				P.T.O. ....	7540165		6834
Blade .....	7540147	3520	6952	Trans. ....	7540124		6857
Drive; W/25" Belt O.C. ....	7540135		6925	<b>44-20139</b>			
Drive; W/31" Belt O.C. ....	7540136		6931	Deck .....	37X63		6601BR
<b>44-1828</b>				Motion Drive .....	37X61		6452BR
Blade; 1970 .....	7540107		6830	<b>130-390</b>			
Blade; 1971 .....	7540145		6488BR	Blade .....	7540107		6830
Eng. To Variator .....	7540147		6952	Trans. ....	7540111	2450	6845
Trans. ....	7540111		6845	<b>130-460</b>			
Variator To Trans. ....	7540136		6931	Blade .....	7540118		6963
<b>44-1829</b>				Trans. ....	7540937	3590	6959
Blade .....	7540118		6963	<b>132-418</b>			
Trans. ....	7540937	3590	6959	Blade .....	7540147	3520	6952
<b>44-1830</b>				Drive; W/25" Belt O.C. ....	7540135		6925
Blade .....	7540935	2310	6831	Drive; W/31" Belt O.C. ....	7540136		6931
Trans. ....	7540111	2450	6845	<b>132-480</b>			
<b>44-1837</b>				Blade .....	7540151		6967
Blade .....	7540147		6952	Drive; W/31" Belt O.C. ....	7540136		6931
Variator To Trans. ....	7540136		6931	Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>44-1850</b>				<b>132-495</b>			
Blade .....	7540151		6967	Blade .....	7540145		6488BR
Drive; W/31" Belt O.C. ....	7540136		6931	Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950	Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>44-1853</b>				<b>133-460</b>			
Blade .....	7540145		6488BR	Blade .....	7540151		6967
Drive; W/31" Belt O.C. ....	7540136		6931	Drive; W/31" Belt O.C. ....	7540136		6931
Drive; W/50" Belt O.C. ....	7540138	3500	6950	Drive; W/50" Belt O.C. ....	7540138	3500	6950
<b>44-1861</b>				<b>140-665</b>			
Trans. ....	7540107		6830	Gen. ....	7540134	7330	
<b>44-1864; 44-1865</b>				Trans. ....	7540112	3800	6980
Blade .....	7540935	2310	6831	<b>142-960; 142-990</b>			
Trans. ....	7540936		6847	Gen. ....	7540139	7380	
<b>44-1868; 44-1869</b>				P.T.O. ....	7540165		6834
Blade .....	7540935	2310	6831	Trans. ....	7540124		6857
Trans. ....	7540111	2450	6845	<b>143-760</b>			
<b>44-1873</b>				Starter/Gen. ....	7540134	7330	
Blade .....	7540118		6963	Trans. ....	7540182		6981
Starter/Gen. ....	7540134	7330		<b>143-960; 143-990; 144-960; 144-990</b>			
Trans.; W/59" Belt O.C. ....	7540937		6959	Gen. ....	7540139	7380	
Trans.; W/61" Belt O.C. ....	7540115		6961	P.T.O. ....	7540165		6834
<b>44-1878</b>				Trans. ....	7540124		6857
Gen. ....	7540134	7330		<b>360-131</b>			
Trans. ....	7540112	3800	6980	Blade .....	7540935	2310	6831
<b>44-1881</b>				Trans. ....	7540936		6847
Trans. ....	7540112	3800	6980	<b>380-131</b>			
<b>44-1883; 44-1893</b>				Blade .....	7540935	2310	6831
Gen. ....	7540134	7330		Trans. ....	7540111	2450	6845
Trans. ....	7540112	3800	6980	<b>660-131</b>			
				Cross Drive .....	37X66		6475BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TRACTOR SUPPLY - Continued</b>			
<b>660-131 - Continued</b>			
Trans .....	7540112	3800	6980
<b>30560X60 (44-20024); 30562A</b>			
Blade .....	37X57		6498BR
Drive .....	37X65		6453BR
<b>31602X60 (44-20236)</b>			
Drive .....	37X61		6452BR
<b>38611X60; 40703X60 (44-20163)</b>			
Blade .....	37X62		6400BR
Drive .....	37X61		6452BR
<b>42815X60 (44-20032); 42822X60 (44-19861)</b>			
Drive .....	37X61		6452BR
<b>46370X60 (44-20278)</b>			
Blade .....	37X69		6508BR
Cross Drive .....	37X66		6475BR
<b>46802X60 (44-20040)</b>			
Blade .....	37X69		6508BR
Cross Drive .....	37X66		6475BR
Drive .....	37X61		6452BR
<b>46903X60 (44-19687)</b>			
Cross Drive .....	37X66		6475BR
<b>90560X60 (44-20024)</b>			
Blade .....	37X57		6498BR
Drive .....	37X65		6453BR
<b>B3601-040 (44-20430)</b>			
Blade .....	305698		6873
Drive .....	300575		6836
<b>B3912-230 (44-20105)</b>			
Blade .....			6978
Drive .....	54758		6551BR
<b>B4514-010 (44-20210)</b>			
Blade .....	300142		6841
Cross Drive .....			6978
Drive .....			6885
<b>B4518-080 (44-20252)</b>			
Blade .....	300142		6841
Cross Drive .....			6975
Drive .....	302719		6891
<b>B4616-030 (44-20308)</b>			
Cross Drive .....	302291		6964
Drive .....	303241		6890
<b>C3601-020 (44-20430)</b>			
Drive .....	300575		6836
<b>C3912-080 (44-20105)</b>			
Blade .....			6978
Drive .....	54758		6551BR
<b>C4314-010 (44-20197)</b>			
Drive .....	314572		6880
<b>D3601-030 (44-20430)</b>			
Drive .....	300575		6836
<b>D3812-110 (44-20553)</b>			
Blade .....			6978
<b>D4314-080 (44-20411)</b>			
Drive .....	314572		6880
<b>TS1844A (44-20537)</b>			
Blade .....	106085		6879
Drive .....	123796		6881
<b>TS2051A/B (44-20294)</b>			
Blade .....	110884		6714BR
Drive .....	110883		6893
<b>TROY BILT</b>			
<b>1-732R5</b>			
Deck .....	30392		6958
Trans .....	30425		6871

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TROY BILT - Continued</b>			
<b>1-832R3 Recoil</b>			
Blade .....	30315		6846
Deck .....	30329		6939
Trans .....	30334		6870
<b>1-832R4; 1-832R7</b>			
Deck .....	30392		6958
Trans .....	30425		6871
<b>2-832R3</b>			
Blade .....	30315		6846
Deck .....	30329		6939
Trans .....	30334		6870
<b>3-832DE4; 3-832DE5; 3-832DE7</b>			
Deck .....	30392		6958
Trans .....	30425		6871
<b>3-832R3</b>			
Blade .....	30315		6846
Deck .....	30329		6939
Trans .....	30334		6870
<b>6-103DE6X</b>			
Deck .....	30421		6963
Trans .....	30422		6876
<b>6-1036DE6</b>			
Deck .....	30421		6963
Trans .....	30477		6880
<b>6-1036E4</b>			
Deck .....	30392		6958
Trans .....	30425		6871
<b>6-1036ES</b>			
Deck .....	30421		6963
Trans .....	30477		6880
<b>6-1063E7</b>			
Deck .....	30421		6963
Trans .....	30422		6876
<b>7-1036DE4</b>			
Deck .....	30392		6958
Trans .....	30425		6871
<b>7-1036DE5; 7-1036DE6</b>			
Deck .....	30421		6963
Trans .....	30477		6880
<b>7-1036DE6X; 7-1036DE7</b>			
Deck .....	30421		6963
Trans .....	30422		6876
<b>13A8A1BS066</b>			
Deck Drive .....	954-05021		7014BR
Drive .....	954-05027B		6711BR
<b>13A9A1KN066</b>			
Deck Drive .....	954-05087A		7055BR
Drive .....	954-05027B		6711BR
<b>13A226JD066</b>			
Deck Drive .....	954-04318		6945
Lower Drive .....	954-04331		6935
Upper Drive .....	954-0241A		6494BR
<b>13A277BS066</b>			
Deck Drive .....	954-04060C		6776BR
Trans. - Lower .....	954-04249A		6520BR
Trans. - Upper .....	954-05040		7050BR
<b>13A277KS066</b>			
Deck Drive .....	954-04060C		6776BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-05040		7050BR
<b>13A278KS066</b>			
Deck Drive .....	954-04060B		6776BR
Drive - Lower .....	954-0467A		6606BR
Drive - Upper .....	954-04208A		7051BR
<b>13A279KS066</b>			
Deck Drive .....	954-04060B		6776BR
Drive .....	95404252		6884



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TROY BILT - Continued</b>			
<b>13A726JD066</b>			
Deck Drive .....	954-05001		6975BR
Trans. - Lower .....	954-04331		6935
Trans. - Upper .....	954-05040		7050BR
<b>13A879KS066</b>			
Deck Drive .....	954-04060C		6776BR
Drive .....	95404252		6884
<b>13AA92KP066</b>			
Deck Drive .....	954-04077		6778BR
Drive .....	954-04207		6879
<b>13AA93KP066</b>			
Deck Drive .....	954-04107		6845BR
Drive .....	954-04297		6518BR
<b>13AAA1BT066</b>			
Deck Drive .....	954-05022A		7053BR
Drive .....	954-05027B		6711BR
<b>13AAA1KT066</b>			
Deck Drive .....	954-04060C		6776BR
Drive .....	954-04297		6518BR
<b>13AAA2KW066; 13AAA2KW266</b>			
Deck Drive .....	95404083		6982BR
Drive .....	95404244A		6877
<b>13AAA93KT066</b>			
Deck Drive .....	95404219		6651BR
Drive .....	954-04297		6518BR
<b>13AC21JD011</b>			
Deck Drive .....	954-05001		6975BR
Drive .....	954-05130		6545BR
<b>13AC26JD011; 13AC26JD211</b>			
Deck Drive .....	954-04318		6945
Lower Drive .....	954-04331		6935
Upper Drive .....	954-0241A		6494BR
<b>13AK78BS011</b>			
Deck Drive .....	954-04060C		6776BR
Trans. - Lower .....	954-0467A		6606BR
Trans. - Upper .....	954-04208A		7051BR
<b>13AK79BT011</b>			
Deck Drive .....	95404219		6651BR
Drive .....	95404252		6884
<b>13AL78BT066</b>			
Deck Drive .....	95404219		6651BR
Trans. - Lower .....	954-0467A		6606BR
Trans. - Upper .....	954-04208A		7051BR
<b>13AL78KT066</b>			
Deck Drive .....	95404219		6651BR
Drive - Lower .....	954-0467A		6606BR
Drive - Upper .....	954-04208A		7051BR
<b>13AL91KS066</b>			
Deck Drive .....	954-04060B		6776BR
Drive .....	954-04207		6879
<b>13AL93KS066</b>			
Deck Drive .....	954-04060B		6776BR
Drive .....	954-04297		6518BR
<b>13ALA1KS066</b>			
Deck Drive .....	954-05021		7014BR
Drive .....	954-05027A		6524BR
<b>13AM77KS011; 13AM77KS066</b>			
Deck Drive .....	954-04060B		6776BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-05040		7050BR
<b>13AN77BS011</b>			
Deck Drive .....	954-04060C		6776BR
Trans. - Lower .....	954-04249A		6520BR
Trans. - Upper .....	954-05040		7050BR
<b>13AN77KG011</b>			
Deck Drive .....	954-04060C		6776BR
Trans. ....	95404001A		6969

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TROY BILT - Continued</b>			
<b>13AN77KS011; 13AN77KS066; 13AN77KS211</b>			
Deck Drive .....	954-04060B		6776BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-0241A		6494BR
<b>13AQ1BQ011</b>			
Deck Drive .....	954-04077A		6778BR
Drive .....	954-05027B		6711BR
<b>13AQ2BA011; 13AQ2BW011</b>			
Deck Drive .....	954-05025A		6566BR
Drive .....	954-05027B		6711BR
<b>13AQ2KW011</b>			
Deck Drive .....	954-05025		6566BR
Drive .....	954-05027A		6524BR
<b>13AT91KT066</b>			
Deck Drive .....	95404219		6651BR
Drive .....	954-04207		6879
<b>13AT609G766</b>			
Deck Drive .....	754-04060B		6776BR
Lower Drive .....	7540467		6606BR
Upper Drive .....	7540468		6556BR
<b>13AV60KG011</b>			
Deck Drive .....	954-04045		6663BR
Drive - Lower .....	9540467		6606BR
Drive - Upper .....	9540468		6556BR
<b>13AV78KS011; 13AV78KS066</b>			
Deck Drive .....	954-04060C		6776BR
Drive - Lower .....	954-0467A		6606BR
Drive - Upper .....	954-04208A		7051BR
<b>13AX60KH011; 13AX60KH066</b>			
Blade Drive .....	9540349		6637BR
Eng. To Deck .....	95404122		6713BR
Lower Drive .....	7540467		6606BR
Upper Drive .....	7540468		6556BR
<b>13AX60KH211</b>			
Deck Drive .....	75404045		6663BR
Lower Drive .....	7540467		6606BR
Upper Drive .....	7540468		6556BR
<b>13AX60TG766</b>			
Blade Drive .....	9540349		6637BR
Eng. To Deck .....	95404122		6713BR
Lower Drive .....	7540467		6606BR
Upper Drive .....	7540468		6556BR
<b>13B226JD066; 13BC26JD011; 13BC26JD066; 13BC26JD211</b>			
Deck Drive .....	954-05001		6975BR
Lower Drive .....	954-04331		6935
Upper Drive .....	954-0241A		6494BR
<b>13BX60KH011; 13BX60KH211</b>			
Blade Drive .....	9540349		6637BR
Eng. To Deck .....	95404122		6713BR
Lower Drive .....	7540467		6606BR
Upper Drive .....	7540468		6556BR
<b>13BX60TG711; 13BX60TG766</b>			
Deck Drive .....	75404045		6663BR
Lower Drive .....	7540467		6606BR
Upper Drive .....	7540468		6556BR
<b>13BX78KS011; 13BX78KS211</b>			
Deck Drive .....	954-04060B		6776BR
Drive - Lower .....	954-0467A		6606BR
Drive - Upper .....	954-04208A		7051BR
<b>13BX79KT011; 13BX79KT211</b>			
Deck Drive .....	95404219		6651BR
Drive .....	95404252		6884
<b>13CC26JD011</b>			
Deck Drive .....	954-05001		6975BR
Drive - Lower .....	954-04331		6935
Drive - Upper .....	954-05040		7050BR
<b>13CX79KT011</b>			
Deck Drive .....	95404219		6651BR

Lawn & Garden Equipment



# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TROY BILT - Continued</b>			
<b>13CX79KT011 – Continued</b>			
Drive .....	95404252		6884
<b>13WC26JD211</b>			
Deck Drive .....	954-05001		6975BR
Lower Drive .....	954-04331		6935
Upper Drive .....	954-0241A		6494BR
<b>13WM77KS011; 13WM77KS211</b>			
Deck Drive .....	954-04060C		6776BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-05040		7050BR
<b>13WN77KS011; 13WN77KS066; 13WN77KS211</b>			
Deck Drive .....	954-04060B		6776BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-0241A		6494BR
<b>13WQ93KP011</b>			
Deck Drive .....	954-04107		6845BR
Drive .....	954-04297		6518BR
<b>13WQA2KQ011</b>			
Deck Drive .....	954-04077A		6778BR
Drive .....	954-05027A		6524BR
<b>13WQA2KW011</b>			
Deck Drive .....	954-05025		6566BR
Drive .....	954-05027A		6524BR
<b>13WV78KS011; 13WV78KS211</b>			
Deck Drive .....	954-04060C		6776BR
Drive - Lower .....	954-0467A		6606BR
Drive - Upper .....	954-04208A		7051BR
<b>13WX78KS011; 13WX78KS066</b>			
Deck Drive .....	954-04060B		6776BR
Lower Drive .....	954-0467A		6606BR
Upper Drive .....	95404208		7051BR
<b>13WX78KS211</b>			
Deck Drive .....	95404219		6651BR
Lower Drive .....	954-0467A		6606BR
Upper Drive .....	95404208		7051BR
<b>13WX78KT066</b>			
Deck Drive .....	954-04060B		6776BR
Lower Drive .....	954-0467A		6606BR
Upper Drive .....	95404208		7051BR
<b>13WX79BT011; 13WX79KT011; 13WX79KT066; 13WX79KT211</b>			
Deck Drive .....	95404219		6651BR
Drive .....	95404252		6884
<b>13YX78KS011; 13YX78KS211</b>			
Deck Drive .....	954-04060B		6776BR
Drive - Lower .....	954-0467A		6606BR
Drive - Upper .....	954-04208A		7051BR
<b>13YX79KT011; 13YX79KT211</b>			
Deck Drive .....	95404219		6651BR
Drive .....	95404252		6884
<b>14A7A3BA011</b>			
Deck Drive .....	954-05025A		6566BR
Drive .....	954-05027B		6711BR
<b>14AR94KK066; 14BR94KK066</b>			
Deck Drive .....	95404083		6982BR
Drive .....	95404244A		6877
<b>17ADCACK066</b>			
Deck Drive .....	954-04329		6767BR
Hydro. Drive .....	954-04317		6448BR
<b>17ADCACT066</b>			
Deck Drive .....	954-04325		6977BR
Hydro. Drive .....	954-04317		6448BR
<b>17AFCACP011; 17AFCACP211</b>			
Deck Drive .....	954-05008		6873BR
Hydro. Drive .....	954-04317		6448BR
<b>17AFCACS011; 17AFCACS211</b>			
Deck Drive .....	954-04033A		6715BR
Hydro. Drive .....	954-04317		6448BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TROY BILT - Continued</b>			
<b>17AQNAMU066</b>			
Deck Drive .....	954-05158		7029BR
Drive .....	954-05336		6793BR
<b>17ARCACK011</b>			
Deck Drive .....	954-04329		6767BR
Drive .....	954-04317A		6448BR
<b>17ARCACP011; 17ARCACP211</b>			
Deck Drive .....	954-05008		6873BR
Drive .....	954-04317A		6448BR
<b>17ARCACQ011; 17ARCACQ211</b>			
Deck Drive .....	954-05078		7057BR
Drive .....	954-04317A		6448BR
<b>17ARCACS011</b>			
Deck Drive .....	954-04033A		6715BR
Drive .....	954-04317A		6448BR
<b>17ARCACT011</b>			
Deck Drive .....	954-04325		6977BR
Drive .....	954-04317A		6448BR
<b>17ARCACW011</b>			
Deck Drive .....	954-04329A		6692BR
Drive .....	954-04317A		6448BR
<b>17ARCBDT011; 17ARCBDT066</b>			
Deck Drive .....	954-04325		6977BR
Drive .....	954-04317A		6448BR
<b>17ARCBDW011; 17ARCBDW066</b>			
Deck Drive .....	954-04329A		6692BR
Drive .....	954-04317A		6448BR
<b>17BDCACK066</b>			
Deck Drive .....	954-04329		6767BR
Drive .....	954-04317A		6448BR
<b>17BDCACW066</b>			
Deck Drive .....	954-04329A		6692BR
Drive .....	954-04317A		6448BR
<b>17WFCACP011</b>			
Deck Drive .....	954-05008		6873BR
Hydro. Drive .....	954-04317		6448BR
<b>17WFCACS011</b>			
Deck Drive .....	954-04033A		6715BR
Hydro. Drive .....	954-04317		6448BR
<b>17WRCACS011</b>			
Deck Drive .....	954-04033A		6715BR
Drive .....	954-04317A		6448BR
<b>321HRS</b>			
Trans. ....	1751597		6891
<b>732R6; 832DE6; 832E6</b>			
Deck .....	30392		6958
Trans. ....	30425		6871
<b>3016HR; 3016HRS</b>			
Trans. ....	1751597		6891
<b>3114GR</b>			
Trans. ....	1747188		6897
<b>3114HR</b>			
Trans. ....	1751597		6891
<b>3212GR; 3214GR; 3312GR; 3312GRS</b>			
Trans. ....	1747188		6897
<b>3312HR; 3312HRS</b>			
Trans. ....	1751597		6891
<b>13025; 13026</b>			
Trans. ....	1747188		6897
<b>13027; 13028; 13064; 13065; 13066</b>			
Trans. ....	1751597		6891



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TRU-TEST</b>			
<b>5020T; 5020T2; 5021T; 5051T2; 5051TE; 5061TE</b>			
Blade .....	20843B		6825
Trans. ....	20843A		6829
<b>5080E</b>			
Blade .....	20843T		6863
Drive .....	20843V		6850
Spindle .....	20843W		6859
<b>5081TXE</b>			
Blade; W/59" Belt O.C. ....	20843W		6859
Blade; W/63" Belt O.C. ....	20843T		6863
Drive .....	20843X		6870
<b>6752TR #44</b>			
Blade .....	31050G		6836
Drive .....	20843V		6850
<b>6782TXE</b>			
Drive .....	20843X		6870
<b>7742TR</b>			
Drive .....	20843L		6835
<b>7772TE</b>			
Blade .....	20843J		6860
Drive .....	20843L		6835
<b>UNICO</b>			
<b>134-585</b>			
Drive .....	7540136		6931
Eng. To Variator .....	7540157		6928
<b>135-497</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540191		6865
Variator To Trans. ....	7540173	3370	6937
<b>138-330</b>			
Belt; W/30" Belt O.C. ....	7540107		6830
<b>138-380; 138-390</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>138-460</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>148-650; 148-655; 148-660; 148-665; 148-668</b>			
Belt; W/7 H.P. Eng. ....	7540112	3800	6980
<b>148-760; 148-860</b>			
Belt; W/33 1/2" Belt O.C. ....	7540123		3V335
Belt; W/57" Belt O.C. ....	7540124		6857
<b>340-015; 360-015</b>			
Blade .....	7540935		6831
Deck .....	7540230		6755BR
Drive; W/Turf Trac Drive .....	7540245		6859
Trans. ....	7540936		6847
Transaxle .....	7540255		6837
<b>650-15; 650-16</b>			
Belt; W/80" Belt O.C. ....	7540112	3800	6980
<b>2383-41</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540191		6865
Variator To Trans. ....	7540173	3370	6937
<b>2503; 2513</b>			
Trans. ....	20716		6837
<b>3013; 3033; 3043; 3063</b>			
Blade; W/41" Belt O.C. ....	20555		6841
Blade; W/48" Belt O.C. ....	20556		6848
Trans. ....	20716		6837
<b>3213; 3233</b>			
Blade .....			6863
Trans. ....	20716		6837
<b>3241</b>			
Blade .....	7540935	2310	6831

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>UNICO - Continued</b>			
<b>3241 - Continued</b>			
Trans. ....	7540936		6847
<b>3241-0</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>3251</b>			
Blade .....	7540111	2450	6845
Trans. ....	7540107		6830
<b>3252</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>3253</b>			
Eng. ....	7540147	3520	6952
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>3254; 3254-1; 3254-2; 3254-3</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>3255; 3255-1; 3255-2; 3255-3</b>			
Eng. ....	7540147	3520	6952
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>3255-43; 3256-43</b>			
Blade .....	20717		6856
Trans. ....	20716		6837
<b>3261-01 Turf Flite</b>			
Blade .....	7540188		6951
Trans.; W/24" Belt O.C. ....	7540187	3240	
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>3261-41; 3261-51</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>3261-61 Turf Flite; 3262-41 Turf Flite; 3262-51 Turf Flite; 3263-51 Turf Flite</b>			
Blade .....	7540188		6951
Trans.; W/24" Belt O.C. ....	7540187	3240	
Trans.; W/31" Belt O.C. ....	7540136		6931
<b>3264-61; 3264-71</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>3265-61; 3265-71</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>3265-81</b>			
Blade .....	7540107		6830
Trans. ....	7540936		6847
<b>3301; 3302</b>			
Blade .....	7540127		6966
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>3303</b>			
Blade; W/31" Belt O.C. ....	7540935	2310	6831
Blade; W/63" Belt O.C. ....	7540118		6963
Starter/Gen. ....	7540134	7330	
Trans.; W/45" Belt O.C. ....	7540111	2450	6845
Trans.; W/59" Belt O.C. ....	7540937	3590	6959
<b>3304</b>			
Blade .....	7540118		6963
Starter/Gen. ....	7540134	7330	
Trans. ....	7540937	3590	6959
<b>3305; 3306; 3306-41</b>			
Blade .....	7540127		6966
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>3306-43</b>			
Blade; W/41" Belt O.C. ....	20555		6841
Blade; W/48" Belt O.C. ....	20556		6848
Trans. ....	20716		6837

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>UNICO - Continued</b>			
<b>3307-3; 3307-41</b>			
Blade .....	7540167		6964
Trans. ....	7540164	2630	6863
<b>3307-51; 3307-61; 3307-71; 3307-81; 3308-51; 3308-61</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>3309-01 Turf Trac; 3309-81 Turf Trac; 3309-91 Turf Trac</b>			
Drive; W/42" Belt O.C. ....	7540207		6842
Drive; W/62" Belt O.C. ....	7540198		6451BR
<b>3341</b>			
Blade .....	7540145		6488BR
Eng. ....	7540147	3520	6952
Trans. ....	7540136		6931
<b>3341-01 Turf Trac; 3342 Turf Trac; 3342-01 Turf Trac</b>			
Blade .....	7540151		6967
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>3343</b>			
Blade .....	7540127		6966
Trans. ....	7540166	3620	6962
<b>3344</b>			
Blade .....	7540151		6967
Deck .....	7540138	3500	6950
Traction .....	7540136		6931
<b>3345-41</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540185		6849
<b>3345-51; 3345-61; 3345-71</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540200		6848
<b>3346-51</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>3347-81 Turf</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>3381; 3381-03</b>			
Blade .....	7540145		6488BR
Eng. ....	7540147	3520	6952
Trans. ....	7540136		6931
<b>3381-71</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540191		6865
Variator To Trans. ....	7540173	3370	6937
<b>3382; 3382-0</b>			
Blade .....	7540145		6488BR
Eng. ....	7540147	3520	6952
Trans. ....	7540136		6931
<b>3383-01 Turf</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>3383-3</b>			
Blade .....	7540145		6488BR
Trans. ....	7540127		6966
<b>3383-41</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540191		6865
Variator To Trans. ....	7540173	3370	6937
<b>3383-51</b>			
Blade .....	7540145		6488BR
Variator To Trans. ....	7540173	3370	6937
<b>3383-61</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540191		6865
Variator To Trans. ....	7540173	3370	6937

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>UNICO - Continued</b>			
<b>3383-81 Turf; 3383-91 Turf</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>3384-61; 3384-71</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540191		6865
Variator To Trans. ....	7540173	3370	6937
<b>3384-81 Turf; 3384-91 Turf</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>3441-01 Turf Trac</b>			
Deck; W/Optional 44" Deck .....			6856
Drive .....	7540245		6859
Transaxle .....	7540255		6837
<b>3613; 3633; 3633-43</b>			
Blade; W/46" Belt O.C. ....			6846
Blade; W/64" Belt O.C. ....	20558		6864
Trans. ....	20716		6837
<b>4071; 4072; 4082; 4082-1; 4082-2</b>			
Blade .....	7540113	3480	6948
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>4082-3</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>4101</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>4102-3; 4103-41; 4103-51; 4103-61</b>			
Blade .....	7540184		6852
Deck .....	7540180		6510BR
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>4104-71</b>			
Trans. ....	7540182	3810	6981
<b>4105-71</b>			
Trans. ....	7540217		6979
<b>4106-71</b>			
Eng. To Variator .....	7540218		6959
Variable Speed To Trans. ....	7540211		6946
<b>4114-81</b>			
Trans. ....	7540182	3810	6981
<b>4115-81</b>			
Trans. ....	7540217		6979
<b>4116-81</b>			
Eng. To Variator .....	7540228		6962
Variator To Trans. ....	7540211		6946
<b>4117-81</b>			
Eng. To Variator .....	7540210		6960
Variator To Trans. ....	7540212		6945
<b>4118-91</b>			
Drive .....	7540245		6859
Transaxle .....	7540243		6846
<b>4121</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>4122; 4131</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540139	7380	
Trans. ....	7540124		6857
<b>4131-3</b>			
Clutch .....	7540124		6857
P.T.O. ....	7540165		6834
<b>4131-41; 4131-51</b>			
Blade .....	7540125		6428BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>UNICO - Continued</b>			
<b>4131-41; 4131-51 - Continued</b>			
Gen. ....	7540139	7380	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>4141; 4142</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>4151</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540139	7380	
Trans. ....	7540124		6857
<b>4152; 4152-2; 4161-61</b>			
Clutch ....	7540124		6857
P.T.O. ....	7540165		6834
<b>4162-3</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540169	7355	
Trans. ....	7540124		6857
<b>4162-51; 4162-61; 4162-71</b>			
Gen. ....	7540169	7355	
P.T.O. ....	7540165		6834
<b>4163-71</b>			
Eng. To Variator ....	7540210		6960
Variator To Trans. ....	7540212		6945
<b>4163-81</b>			
Eng. To Variator ....	7540227		6963
Variator To Trans. ....	7540212		6945
<b>4163-91</b>			
Drive ....	7540217		6979
Transaxle ....	7540212		6945
<b>4164-71</b>			
Eng. To Variator ....	7540218		6959
Variable Speed To Trans. ....	7540211		6946
<b>4164-81</b>			
Eng. To Variator ....	7540228		6962
Variator To Trans. ....	7540211		6946
<b>4165-91</b>			
P.T.O. ....	7540234		6841
<b>4166-01; 4166-91; 4167-01; 4168-01</b>			
Drive ....	7540245		6859
Transaxle ....	7540244		6840
<b>4187-01</b>			
P.T.O. ....	7540234		6841
<b>4262-81</b>			
Gen. ....	7540169	7355	
P.T.O. ....	7540165		6834
<b>4282</b>			
Blade ....	7540113	3480	6948
Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>Turf Trac</b>			
Blade ....	7540145		6488BR
Trans. ....	7540173	3370	6937
<b>UNIVERSAL PROCESS CO.</b>			
<b>770; 771</b>			
Belt; W/32", 36" Deluxe Units Tractor			
Drive ....	T10170	3780	6978
Belt; W/32", 36" Std. Tractor ....	18121	2450	6845
Eng. To Trans. ....	15294	3430	6943
<b>VARI-TRAC</b>			
<b>5 H.P.; 8 H.P.</b>			
Drive; W/37" Belt O.C. ....	3370		6937
Drive; W/38" Belt O.C. ....			6938

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WALKER</b>			
<b>C</b>			
Eng. To Gear Box; W/16 H.P. Kohler Eng. ....	6230		3VX425
<b>M36-42</b>			
Eng. ....	52301		6932
P.T.O.; W/35" Belt O.C. ....			6935
P.T.O.; W/45" Belt O.C. ....	52341		6935
<b>MC (GHS); MC (SD)</b>			
Drive; W/16 H.P. Kohler Eng. ....	6230		3VX425
Ground Drive; W/16 H.P. Kohler Eng. ....	6232		6845
P.T.O.; W/16 H.P. Kohler Eng. ....	6230		3VX425
<b>MC565D</b>			
Blower ....	72341		6668BR
Ground Drive ....	7248		6669BR
J.S. ....	6250		6667BR
P.T.O. ....	8230		6670BR
<b>MDDGHS</b>			
Blower ....	7234-2		6841BR
Eng. ....	REMF1320	7320	
Ground Drive ....	7248		6669BR
J.S. ....	6231		3VX355
<b>MS (GHS)</b>			
Drive; W/B. & S. 11 H.P. Eng. ....	52302		6932
Ground Drive; W/B. & S. 11 H.P. Eng. ....	5232		6847
P.T.O.; W/B. & S. 11 H.P. Eng. ....	52342		6944
<b>MS (SD)</b>			
Belt; W/B. & S. 11 H.P. Eng. ....	52302		6932
Ground Drive; W/B. & S. 11 H.P. Eng. ....	5232		6847
P.T.O.; W/B. & S. 11 H.P. Eng. ....	52341		6935
<b>MT48GHS20; MT48GHS26</b>			
Blower ....	72341		6668BR
Ground Drive ....	7248		6669BR
J.S. ....	6250		6667BR
P.T.O. ....	8230		6670BR
<b>MT62SD20; MT62SD26</b>			
Ground Drive ....	7248		6669BR
J.S. ....	6250		6667BR
P.T.O. ....	8230		6670BR
<b>MTGHS23A; MTGHS26A; MTL48GHS; MTL48GHS25; MTL48GHS29; MTL62GHS31</b>			
Blower ....	72341		6668BR
Ground Drive ....	7248		6669BR
J.S. ....	6250		6667BR
P.T.O. ....	8230		6670BR
<b>MTL62SD; MTL62SD29; MTL62SD31</b>			
Ground Drive ....	7248		6669BR
J.S. ....	6250		6667BR
P.T.O. ....	8230		6670BR
<b>MTLGHS25A; MTLGHS31A</b>			
Blower ....	72341		6668BR
Ground Drive ....	7248		6669BR
J.S. ....	6250		6667BR
P.T.O. ....	8230		6670BR
<b>MTLSD25; MTSD23</b>			
Ground Drive ....	7248		6669BR
J.S. ....	6250		6667BR
P.T.O. ....	8230		6670BR
<b>S</b>			
Blower ....	52342		6944
P.T.O. ....	52302		6932
Pump ....			6847
<b>WEGELE</b>			
<b>24" Deluxe; 24" Std.</b>			
Blade ....		3640	6964
Drive; Hydro. Model ....		3450	6945
Trans.; W/T92 Trans. ....		3490	6949
<b>30" Deluxe</b>			
Blade ....		2600	6860
Drive; Hydro. Model ....		3470	6947

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WEGELE - Continued</b>			
<b>30" Std.</b>			
Blade; Early; W/T92 Trans. ....		2620	6862
Blade; Late; W/T92 Trans. ....		2600	6860
Trans.; W/T92 Trans. ....		3490	6949
<b>36" Deluxe</b>			
Blade .....		2620	6862
Drive; Hydro. Model .....		3470	6947
<b>36" Std.</b>			
Blade; W/62" Belt O.C.; W/T92 Trans. ...		2620	6862
Blade; W/63" Belt O.C.; W/T92 Trans. ...			6964
Drive; Hydro. Model .....		3470	6947
Trans.; W/T92 Trans. ....		3490	6949
<b>2400</b>			
Blade .....		3640	6964
Trans. ....		3490	6949
<b>5000</b>			
Blade .....		3620	6962
Drive .....		3470	6947
<b>6300 Series</b>			
Blade .....		3630	6963
Trans. ....		3480	6948
<b>WESTERN AUTO</b>			
<b>2X7200</b>			
Belt .....	7540936		6847
Blade .....	7540107		6830
<b>2X7220</b>			
Blade .....	7540147	3520	6952
Eng. To Variator .....	7540135		6925
Variator To Trans. ....	7540136		6931
<b>2X7442; 2X7445</b>			
Blade .....	7540151		6967
Eng. To Variator .....	7540138	3500	6950
Variator To Trans. ....	7540136		6931
<b>2X7610</b>			
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>2X7620</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540139	7380	
Trans. ....	7540124		6857
<b>2X7625</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540169	7355	
Trans. ....	7540124		6857
<b>2XC107</b>			
Trans. ....	7540107		6830
<b>2XC2631; 2XC2731</b>			
Blade .....	55019		6833
Speed Selector To Trans. ....	57051	2540	6854
<b>2XC3245</b>			
Traction .....	4320	2338	
<b>2XC3345</b>			
Belt; W/30" Belt O.C. ....	4638		6830
<b>2XC3444</b>			
Belt; W/31" Belt O.C. ....	7540935	2310	6831
Belt; W/47" Belt O.C. ....	7540936		6847
<b>2XC3445</b>			
Belt; W/30" Belt O.C. ....	4638		6830
<b>2XC3544</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936		6847
<b>2XC3545</b>			
Belt; W/30" Belt O.C. ....	4638		6830
<b>2XC3552</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540108	2460	6846

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>2XC3642A</b>			
Trans. ....	7540107		6830
<b>2XC3652</b>			
Blade .....	7540935	2310	6831
Trans.; W/45" Belt O.C. ....	7540111	2450	6845
Trans.; W/47" Belt O.C. ....	7540936		6847
<b>2XC3654</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>2XC3656</b>			
Blade .....	10923		6830
Traction .....	10897		6851
<b>2XC3660</b>			
Belt; W/80" Belt O.C. ....	7540112	3800	6980
<b>2XC3661</b>			
Blade .....	7540113	3480	6948
<b>2XC3665</b>			
Drive .....	11144		6835
Trans. ....			6852
<b>2XC3666</b>			
Mower .....	9303		6725
<b>2XC3752</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936		6847
<b>2XC3754</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540111	2450	6845
<b>2XC3755; 2XC3756</b>			
Blade .....	10923		6830
Traction .....	10897		6851
<b>2XC3757</b>			
Blade .....	7540118		6963
Trans.; W/59" Belt O.C. ....	7540937	3590	6959
Trans.; W/61" Belt O.C. ....	7540115	3610	6961
<b>2XC3760</b>			
Starter/Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>2XC3765</b>			
Drive .....	11144		6835
Eng. To J.S. ....	11144		6835
Trans. ....			6852
<b>2XC3767; 2XC3769</b>			
Mower .....	9303		6725
<b>2XC3788</b>			
Auger .....	13009	2410	6841
Traction .....	13009	2410	6841
<b>2XC3862</b>			
Belt; W/80" Belt O.C. ....	7540112	3800	6980
<b>2XC3868</b>			
Drive .....	11144		6835
Trans. ....			6852
<b>2XC3953</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>2XC3954</b>			
Blade .....	7540105		6830
Trans. ....	7540111	2450	6845
<b>2XC3956</b>			
Blade .....	7540127		6966
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>2XC3957; 2XC3958</b>			
Blade .....	7540118		6963
Trans. ....	7540937	3590	6959
<b>2XC3970</b>			
Drive .....	11144		6835





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>2XC3970 – Continued</b>			
Trans. ....			6852
<b>2XC4222</b>			
Blade; 1972 .....	7540138	3500	6950
Blade; 1973 .....	7540147	3520	6952
Eng. To Variator; 1973 .....	7540135		6925
Trans.; 1972 .....	7540101		6517BR
<b>2XC5200</b>			
Blade .....		2300	6830
Trans. ....	7540936		6847
<b>2XC5210</b>			
Blade .....	20717		6856
Trans. ....	20716		6837
<b>2XC5215</b>			
Blade .....	7540147	3520	6952
Eng. To Variator .....	7540135		6925
Variator To Trans. ....	7540136		6931
<b>2XC5320</b>			
Blade .....	7540107		6830
Trans. ....	7540111	2450	6845
<b>2XC5325</b>			
Blade .....	20717		6856
Trans. ....	20716		6837
<b>2XC5440</b>			
Blade; W/66" Belt O.C. ....	7540127		6966
Blade; W/69" Belt O.C. ....	7540145		6488BR
Eng. To Variator .....	7540147	3520	6952
Variator To Trans. ....	7540136		6931
<b>2XC5450</b>			
Blade; W/44" Belt O.C. ....	21059		6844
Blade; W/63" Belt O.C. ....	21058		6863
Drive .....	20716		6837
<b>2XC5460</b>			
Blade; W/66" Belt O.C. ....	7540127		6966
Blade; W/69" Belt O.C. ....	7540145		6488BR
Eng. To Variator .....	7540147	3520	6952
Variator To Trans. ....	7540136		6931
<b>2XC7200</b>			
Belt .....	7540936		6847
Blade .....	7540107		6830
<b>2XC7204</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>2XC7205</b>			
Blade .....	20717		6856
Drive .....	20715		6837
<b>2XC7206</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540198		6451BR
<b>2XC7220; 2XC7222</b>			
Blade .....	7540147	3520	6952
Eng. To Variator .....	7540135		6925
Variator To Trans. ....	7540136		6931
<b>2XC7320; 2XC7340; 2XC7342</b>			
Blade .....	7540151		6967
Eng. To Variator .....	7540138	3500	6950
Variator To Trans. ....	7540136		6931
<b>2XC7410</b>			
Blade .....	7540195		6854
Drive .....	7540164	2630	6863
Trans. ....	7540198		6451BR
<b>2XC7422</b>			
Blade .....	7540178	3820	6982
Trans.; 1973 .....	7540179		6950
Trans.; 1974 .....	7540185		6849
Trans.; 1975 .....	7540200		6848
<b>2XC7424</b>			
Blade .....	7540145		6488BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>2XC7424 – Continued</b>			
Drive .....	7540127		6966
J.S. ....	7540191		6865
Trans. ....	7540173	3370	6937
<b>2XC7425</b>			
Drive; W/28" Belt O.C. ....	7540157	3280	
Drive; W/29" Belt O.C. ....	7540183	3290	6929
Trans. ....	7540136		6931
<b>2XC7430</b>			
Blade .....	7540127		6966
Trans. ....	7540166	3620	6962
<b>2XC7440</b>			
Blade .....	7540151		6967
Eng. To Variator .....	7540138	3500	6950
Variator To Trans. ....	7540136		6931
<b>2XC7442</b>			
Blade .....	7540145		6488BR
Trans. ....	7540136	3500	6931
Variable Speed .....	7540138		6950
<b>2XC7445</b>			
Blade .....	7540151		6967
Eng. To Variator .....	7540138	3500	6950
Variator To Trans. ....	7540136		6931
<b>2XC7460</b>			
Blade .....	7540145		6488BR
Eng. To Variable Speed .....	7540147	3520	6952
Variable Speed To Trans. ....	7540136		6931
<b>2XC7551; 2XC7552</b>			
Blade; W/100" Belt O.C. ....	7540181		7014BR
Blade; W/105" Belt O.C. ....	7540125		6428BR
Blade; W/99 5/8" Belt O.C. ....	7540181		7014BR
Drive .....	7540180		6510BR
<b>2XC7608; 2XC7610</b>			
Blade .....	7540184		6852
Eng. To Deck .....	7540180		6510BR
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>2XC7620; 2XC7625</b>			
Drive .....	7540124		6857
Gen.; W/36 1/8" Belt O.C. ....	7540169	7355	
Gen.; W/38 5/8" Belt O.C. ....	7540139	7380	
P.T.O. ....	7540165		6834
<b>2XF3668; 2XF3768</b>			
Drive .....	11144		6835
Trans. ....			6852
<b>2XF3769</b>			
Mower .....	9303		6725
<b>2XF3870</b>			
Drive .....	11144		6835
Trans. ....			6852
<b>2XF3962</b>			
Blade .....	7540113	3480	6948
Trans. ....	7540112	3800	6980
<b>2XF3968</b>			
Drive .....	11144		6835
Trans. ....			6852
<b>2XF5508</b>			
Blade .....	7540113	3480	6948
Drive; W/41" Belt O.C. ....	11144		6835
Drive; W/80" Belt O.C. ....	7540112	3800	6980
Gen. ....	7540134	7330	
Trans. ....			6852
<b>2XF5510</b>			
Drive .....	16348		6838
Trans. ....			6852
<b>2XF5511</b>			
Mower .....	9303		6725

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>2XF5514</b>			
Drive .....	16348		6838
Trans. ....			6852
<b>2XF5520</b>		7380	
Drive .....	7540124		6857
Gen. ....	7540139		6428BR
Mower .....	7540125		3V335
P.T.O. ....	7540123		
<b>2XF7425</b>			
Eng. To Variator; W/Battery Power .....	7540157		6928
Variator To Trans.; W/Battery Power .....	7540136		6931
<b>2XF7508</b>		3480	6948
Blade .....	7540113		6980
Drive .....	7540112		7330
Gen. ....	7540134		
<b>2XF7510; 2XF7520</b>		7380	
Gen. ....	7540139		3V335
P.T.O. ....	7540123		6857
Trans. ....	7540124		
<b>2XF7521</b>			6428BR
Deck .....	7540125		
<b>2XF7525</b>			3V335
P.T.O. ....	7540123		
<b>2XF7551</b>			6428BR
Deck .....	7540125		
<b>2XF7552</b>			7014BR
Blade .....	7540181		6510BR
Eng. To Deck .....	7540180		
<b>2XF7608</b>		7330	6852
Blade .....	7540184		6510BR
Eng. To Deck .....	7540180		
Starter/Gen. ....	7540134	7330	6981
Trans. ....	7540182	3810	
<b>93-7202-0</b>			6847
Belt .....	7540936		6830
Blade .....	7540107		
<b>93-7206-1</b>		3500	6950
Blade .....	7540138		6451BR
Trans. ....	7540198		
<b>93-7230-1</b>			6951
Blade .....	7540188		6517BR
Trans. ....	7540101		
<b>93-7260-8; 93-7264-4</b>			6964
Blade .....	7540167		6451BR
Trans. ....	7540198		
<b>93-7280-6</b>			6842
Drive; W/42" Belt O.C. ....	7540207		6451BR
Drive; W/62" Belt O.C. ....	7540198		
<b>93-7300-2</b>			6967
Blade .....	7540151		6865
Trans. ....	7540191		
<b>93-7302-8</b>			6488BR
Blade .....	7540145		6865
Eng. To J.S. ....	7540191		6937
J.S. To Trans. ....	7540173	3370	
<b>93-7310-1</b>			6967
Blade .....	7540151		6865
Trans. ....	7540191		
<b>93-7400-0</b>			6488BR
Blade .....	7540145		6551BR
Trans. ....	7540226		
<b>93-7410-9</b>			6854
Blade .....	7540195		6451BR
Trans. ....	7540198		
<b>93-7420-8</b>			6488BR
Blade .....	7540145		6865
Eng. To J.S. ....	7540191		

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>93-7420-8 - Continued</b>			
J.S. To Trans. ....	7540173	3370	6937
<b>93-7600-5</b>			6979
Trans. ....	7540217		
<b>93-7620-3</b>			6834
P.T.O. ....	7540165		6857
Trans. ....	7540124		
<b>93-7630-2</b>			6959
Eng. To Variator .....	7540218		6946
Variator To Trans. ....	7540211		
<b>93-7635-1</b>		7355	
Gen. ....	7540169		6834
P.T.O. ....	7540165		
<b>133-360</b>			6847
Belt .....	7540936		6830
Blade .....	7540107		
<b>133-430; 133-435</b>			6966
Blade .....	7540127		6931
Trans. ....	7540136		6925
Variable Speed .....	7540135		
<b>133-460; 133-462; 133-465</b>			6967
Blade .....	7540151		6950
Eng. To Variator .....	7540138	3500	6931
Variator To Trans. ....	7540136		
<b>138-390</b>			2310
Blade .....	7540935		6831
Trans. ....	7540111	2450	6845
<b>138-460</b>			6963
Blade .....	7540118		6959
Trans. ....	7540937	3590	
<b>143-660</b>			6852
Blade .....	7540184		6510BR
Eng. To Deck .....	7540180		
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>143-760</b>			7330
Starter/Gen. ....	7540134	3810	6981
Trans. ....	7540182		
<b>143-960</b>			6834
P.T.O. ....	7540165		7380
Starter/Gen. ....	7540139		6857
Trans. ....	7540124		
<b>143-990</b>			6834
P.T.O. ....	7540165	7355	6857
Starter/Gen. ....	7540169		
Trans. ....	7540124		
<b>7119A98</b>			6630BR
Blade .....	7540329		
<b>7209A98</b>			6482BR
Blade .....	7540364		6431BR
Variator .....	7540248		
<b>6088101</b>			6830
Blade .....	10923		6851
Traction .....	10897		
<b>6095904; 6095972; 6095990</b>			6830
Belt; W/30" Belt O.C. ....	4638		
<b>GIS3665; GIS3668; GIS3765; GIS3768;</b>			6835
<b>GIS3868; GIS3870; GIS3968; GIS3970</b>			6852
Drive .....	11144		
Trans. ....			
<b>GIS5510; GIS5514</b>			6838
Drive .....	16348		6852
Trans. ....			
<b>GIS7120</b>			6378
Traction .....	216594		



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>GIS7602</b>			
Drive .....	18263		6844
<b>GIS7710; GIS7715</b>			
Eng. To Deck .....	213676		6885
<b>MOM5325</b>			
Blade .....	20717		6856
Trans. ....	20716		6837
<b>MOM5450</b>			
Cross Drive .....	21059		6844
Deck .....	21058		6863
Traction .....	20716		6837
<b>MOM6052A09</b>			
Blade .....	37X12		6449BR
Trans. ....	37X65		6453BR
<b>MOM6084A09</b>			
Blade .....	37X57		6498BR
<b>MOM7000A88</b>			
Blade .....	37X12		6449BR
Traction .....	37X38		6425BR
<b>MOM7002A88</b>			
Blade .....	37X51		6376
Traction .....	37X57		6498BR
<b>MOM7006A88</b>			
Traction .....	37X51		6376
<b>MOM7012A88</b>			
Blade .....	37X51		6376
Traction .....	37X57		6498BR
<b>MOM7016A88</b>			
Traction .....	37X51		6376
<b>MOM7210</b>			
Blade .....	20717		6856
Trans. ....	20716		6837
<b>MTD5200</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>MTD5215</b>			
Blade .....	7540147	3520	6952
Eng. To Variator .....	7540135		6925
Variator To Trans. ....	7540136		6931
<b>MTD5232</b>			
Blade .....	7540127		6966
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>MTD5320</b>			
Blade .....	7540107		6830
Trans. ....	7540111	2450	6845
<b>MTD5330; MTD5332; MTD5335; MTD5336</b>			
Blade .....	7540127		6966
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>MTD5440; MTD5460</b>			
Blade .....	7540145		6488BR
Eng. To Variable Speed .....	7540147	3520	6952
Variable Speed To Trans. ....	7540136		6931
<b>MTD5506</b>			
Blade .....	7540113	3480	6948
Gen. ....	7540134		7330
Trans. ....	7540112		3800
<b>MTD5520</b>			
Blade .....	7540125		6428BR
P.T.O. ....	7540123		3V335
<b>MTD7111A68</b>			
Deck .....	7540145		6488BR
Eng. To V.S. ....	7540280		6447BR
V.S. To Trans. ....	7540281		6405BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>MTD7115A78</b>			
Blade .....	7540329		6630BR
<b>MTD7119A88</b>			
Blade .....	7540349		6637BR
Deck .....	7540350		6464BR
Variable Speed .....	7540248		6431BR
<b>MTD7128A68</b>			
Blade; W/56" Belt O.C. ....	7540230		6755BR
Blade; W/74" Belt O.C. ....	7540293		6501BR
Transaxle .....	7540245		6859
Variator .....	7540244		6840
<b>MTD7129A98</b>			
Deck .....	7540245		6859
Trans. ....	7540244		6840
<b>MTD7200; MTD7200A37; MTD7200A47; MTD7202A08</b>			
Belt .....	7540936		6847
Blade .....	7540107		6830
<b>MTD7204A47; MTD7204A57</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>MTD7206A47; MTD7206A57</b>			
Blade .....	7540138	3500	6950
Trans. ....	7540164	2630	6863
<b>MTD7220; MTD7220A37; MTD7220A47; MTD7220A57; MTD7222A47</b>			
Blade; W/50" Belt O.C. ....	7540138	3500	6950
Blade; W/52" Belt O.C. ....	7540147	3520	6952
Drive .....	7540101		6517BR
Eng. To Variable Speed .....	7540135		6925
Variable Speed To Trans. ....	7540136		6931
<b>MTD7230A08</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>MTD7260; MTD7262</b>			
Blade .....	7540167		6964
Trans. ....	7540198		6451BR
<b>MTD7280A08</b>			
Drive; W/42" Belt O.C. ....	7540207		6842
Drive; W/62" Belt O.C. ....	7540198		6451BR
<b>MTD7300; MTD7300A57</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>MTD7302</b>			
Blade .....	7540145		6488BR
Drive .....	7540191		6865
Trans. ....	7540173	3370	6937
<b>MTD7332A37; MTD7332A47; MTD7336A37</b>			
Blade .....	7540127		6966
Trans. ....	7540136		6931
Variable Speed .....	7540135		6925
<b>MTD7340A47; MTD7340A57; MTD7342A57</b>			
Blade .....	7540151		6967
Eng. To Variator .....	7540138	3500	6950
Variator To Trans. ....	7540136		6931
<b>MTD7410; MTD7410A57; MTD7410A67; MTD7410A77</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>MTD7422A47</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540179		6950
<b>MTD7424A47; MTD7424A57</b>			
Blade .....	7540145		6488BR
Eng. To J.S. ....	7540191		6865
J.S. To Trans. ....	7540173	3370	6937
<b>MTD7425A47</b>			
Eng. To Variator .....	7540157		6928

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>				<b>WHEEL HORSE - Continued</b>			
<b>MTD7425A47 – Continued</b>				<b>1-0420; 1-0422; 1-0430; 1-0435; 1-0440;</b>			
Variator To Trans. ....	7540136		6931	<b>1-0460; 1-0465; 1-0470; 1-0475; 1-0480</b>			6984
<b>MTD7442A37; MTD7445A37</b>				Drive ..... 7478			
Blade .....	7540151		6967	<b>1-0481; 1-0485; 1-0489; 1-0491; 1-0495;</b>			
Eng. To Variator .....	7540138	3500	6950	<b>1-0510; 1-0511</b>			
Variator To Trans. ....	7540136		6931	Drive ..... 7478			
<b>MTD7460</b>				<b>1-0700</b>			
Blade .....		3500	6950	Drive ..... 517433			
Deck .....	7540151		6967	<b>1-1631; 1-2631</b>			
Trans. ....	7540136		6931	Drive ..... 1576			
<b>MTD7508</b>				<b>1-3741; 1-3745; 1-4631</b>			
Blade .....	7540113	3480	6948	Drive ..... 1576			
Trans. ....	7540112	3800	6980	Trans. .... 9691			
<b>MTD7510; MTD7520</b>				<b>1-4741; 1-4751</b>			
Gen. ....	7540139	7380	6857	Drive ..... 8133			
Transaxle .....	7540124			<b>1-4831</b>			
<b>MTD7604</b>				Drive; W/70" Belt O.C. .... 1576			
Deck .....	7540245		6859	Drive; W/74" Belt O.C. .... 8133			
Trans. ....	7540244		6840	<b>1-4841; 1-4851</b>			
<b>MTD7608</b>				Drive ..... 8133			
Blade .....	7540184		6852	<b>1-6041; 1-6051; 1-6231; 1-6241; 1-6251;</b>			
Deck .....	7540180		6510BR	<b>1-6253; 1-6931</b>			
Trans. ....	7540182	3810	6981	Drive ..... 7473			
<b>MTD7610A37</b>				<b>1-7041; 1-7231; 1-7235; 1-7241; 1-7245;</b>			
Starter/Gen. ....	7540134	7330	6981	<b>1-7251; 1-7252; 1-7253; 1-7255</b>			
Trans. ....	7540182	3810		Drive ..... 7478			
<b>MTD7610A47</b>				<b>1-7441</b>			
Blade .....	7540184		6852	Drive ..... 8160			
Deck .....	7540180		6510BR	Trans. .... 8334			
Trans. ....	7540182	3810	6981	<b>1-7451; 1-7451-2</b>			
<b>MTD7610A57</b>				Trans. .... 8334			
Trans. ....	7540182	3810	6981	<b>1-7452; 1-7453</b>			
<b>MTD7620A37</b>				Drive ..... 7478			
P.T.O. ....	7540165		6834	Trans. .... 8334			
Starter/Gen. ....	7540139	7380	6857	<b>1-7741; 1-7751</b>			
Trans. ....	7540124			Drive ..... 8133			
<b>MTD7620A47; MTD7620A57</b>				Trans. .... 8334			
P.T.O. ....	7540165		6834	<b>1-7841; 1-7851</b>			
Trans. ....	7540124		6857	Drive ..... 8133			
<b>MTD7625A37</b>				<b>1-7931; 1-7932</b>			
P.T.O. ....	7540165		6834	Drive ..... 7478			
Starter/Gen. ....	7540169	7355	6857	<b>1-8741; 1-8745; 1-8751</b>			
Trans. ....	7540124			Trans. .... 8911			
<b>MTD7625A47(Hydro); MTD7625A57; MTD7635</b>				<b>1-8752</b>			
P.T.O. ....	7540165		6834	Blade ..... 8976			
<b>WHEEL HORSE</b>				Mower ..... 8975			
<b>1-0100; 1-0110; 1-0120; 1-0140; 1-0141;</b>				Trans. .... 8911			
<b>1-0145</b>				<b>1-8755</b>			
Drive .....	7473		6982	Trans. .... 8911			
<b>1-0200; 1-0270; 1-0274; 1-0276; 1-0277</b>				<b>1-8756</b>			
Drive .....	8133		6874	Blade ..... 8976			
<b>1-0280; 1-0281; 1-0285; 1-0286</b>				Mower ..... 8975			
Eng. ....	104388		6855	Trans. .... 8911			
Mower .....	104865		6855	<b>2-0102; 2-0112</b>			
Trans. ....	103522		6885	Forward & Reverse ..... 103345			
<b>1-0300; 1-0301; 1-0310; 1-0311; 1-0320;</b>				1250			
<b>1-0340; 1-0350; 1-0353; 1-0354; 1-0356</b>				<b>2-0200 Lawn Ranger</b>			
Drive .....	7473		6982	Trans. .... 8911			
<b>1-0360; 1-0370; 1-0380; 1-0381; 1-0385;</b>				<b>2-0200-6 Lawn Ranger</b>			
<b>1-0391; 1-0395</b>				Drive ..... 1576			
Drive .....	7473		6982	<b>2-0210 Lawn Ranger; 2-0211 Lawn Ranger;</b>			
<b>1-0400; 1-0401</b>				<b>2-0220 Lawn Ranger; 2-0230 Lawn Ranger</b>			
Drive .....	7478		6984	Trans. .... 8911			
<b>1-0410</b>				<b>2-2641</b>			
Drive .....	7473		6982	Drive ..... 8430			
				6859			



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHEEL HORSE - Continued</b>			
<b>2-4300</b>			
Trans. ....	101137		A66
<b>3-0113; 3-0114</b>			
Blade .....	8430		6859
Trans. ....	103345	1250	
<b>11-17KEO1C-175 Twin Auto</b>			
Drive .....	108502		6983
<b>61-07K8; 61-08K8; 61-10K8</b>			
Drive .....	7473		6982
<b>61-10KS</b>			
Drive .....	7478		6984
<b>61-12K8</b>			
Drive .....	7473		6982
<b>61-12KS</b>			
Drive .....	7478		6984
<b>61-16K8</b>			
Drive .....	7473		6982
<b>61-16KS</b>			
Drive .....	7478		6984
<b>61-20RG01</b>			
P.T.O. ....	250105		6840
W.P. ....	251028		6734
<b>62-08BP; 62-10BP</b>			
Drive .....	105477		6840
Mower .....	105476		A78
Trans. ....	103522		6885
<b>71-07K8; 71-08K8; 71-10K8; 71-12K8</b>			
Drive .....	7473		6982
<b>71-12KS</b>			
Drive .....	7478		6984
<b>71-14K8; 71-16K8</b>			
Drive .....	7473		6982
<b>71-16KS</b>			
Drive .....	7478		6984
<b>72-08BP; 72-10BP</b>			
Drive .....	105477		6840
Mower .....	105476		A78
Trans. ....	103522		6885
<b>81-08K8; 81-10K8; 81-12K8</b>			
Drive .....	7473		6982
<b>81-12KS</b>			
Drive .....	7478		6984
<b>81-14K8</b>			
Drive .....	7473		6982
<b>81-14KS</b>			
Drive .....	7478		6984
<b>81-16K8</b>			
Drive .....	7473		6982
<b>81-16KS</b>			
Drive .....	7478		6984
<b>82-08BP; 82-11BP</b>			
Trans. ....	106518		6887
<b>91-08K8; 91-10K8; 91-12K8</b>			
Drive .....	7473		6982
<b>91-12KS</b>			
Drive .....	7478		6984
<b>91-14K8</b>			
Drive .....	7473		6982
<b>91-14KS</b>			
Drive .....	7478		6984
<b>91-16K8</b>			
Drive .....	7473		6982

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHEEL HORSE - Continued</b>			
<b>91-16KS</b>			
Drive .....	7478		6984
<b>92-08BP; 92-11BP</b>			
Trans. ....	106518		6887
<b>93-08EP</b>			
Drive .....	104290	1293	
<b>107</b>			
Drive .....	1576		6870
<b>108-3; 108-4; 108-5; 111-5</b>			
J.S. To Deck .....	110420		6848
Traction .....	110364		6833
<b>112C</b>			
Drive .....			6834
<b>116-6</b>			
Eng. To Deck .....	110420		6848
<b>155; 156; 157</b>			
Blade .....	1555		6844
Drive .....	1576		6870
<b>200 Series</b>			
Trans. ....	108427		6463BR
<b>208-3</b>			
Drive .....	108427		6463BR
<b>208-4; 208-5; 210-5</b>			
Drive .....	114860		6714BR
<b>211-3</b>			
Drive .....	108427		6463BR
<b>211-4</b>			
Drive .....	114860		6714BR
<b>211-5</b>			
Drive .....	108427		6463BR
Eng. To Deck .....	111624		6876
<b>211-6</b>			
Drive .....	108427		6463BR
<b>211-A</b>			
Drive .....	109428		A74
<b>212-5; 212H</b>			
Deck .....	113141		6876
<b>252-H</b>			
Drive .....	109428		A74
<b>257H</b>			
Deck .....	114718		6846
<b>257-H</b>			
Drive .....	109428		A74
<b>308; 310</b>			
Drive .....	7473		6982
<b>310-8</b>			
Deck Drive .....	102742		6378
Eng. To Deck .....	102741		6638BR
<b>312</b>			
Drive .....	7473		6982
P.T.O. ....	9750		6969
<b>312-8</b>			
Deck .....	102742		6378
<b>312-A; 314; 314-A</b>			
Drive .....	7473		6982
<b>340-015; 360-015</b>			
Blade .....	7540935		6831
Deck .....	7540230		6755BR
Drive; W/Turf Trac Drive .....	7540245		6859
Trans. ....	7540936		6847
Transaxle .....	7540255		6837
<b>416</b>			
Drive; W/8-Speed Drive .....	7473		6982

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHEEL HORSE - Continued</b>			
<b>416-8</b>			
Eng. To Deck; W/103 1/4" Belt O.C. ....	102742		6378
Eng. To Deck; W/77" Belt O.C. ....	10242		6877
<b>416-H</b>			
Drive .....	114895		6983
<b>417</b>			
Drive; W/8-Speed Drive .....	7473		6982
<b>417-A</b>			
Drive .....	7473		6982
<b>418-A</b>			
Eng. To Deck .....	10242		6877
<b>418-C; 420-LSE</b>			
Drive .....	7473		6982
<b>502</b>			
Drive .....	1576		6870
<b>516-H; 518-H; 520-20H</b>			
Eng. ....	114895		6983
<b>520-H</b>			
Deck .....	102742		6378
<b>520-HC</b>			
Eng. ....	114895		6983
<b>552; 603; 604; 605; 606; 607</b>			
Drive .....	1576		6870
<b>612-2; 616-2</b>			
Drive .....	116527		6843
<b>633; 653; 654; 655; 656; 657; 673; 701; 702; 704</b>			
Drive .....	1576		6870
<b>718-Z</b>			
Blower .....	50104	2510	6851
Deck .....	30203		6584BR
<b>753; 854; 855; 856; 857; 867</b>			
Drive .....	1576		6870
<b>875; 876; 877</b>			
Drive .....	6146		6872
<b>1045; 1055</b>			
Drive .....	1576		6870
<b>1056; 1057; 1067</b>			
Drive .....	1586		6876
<b>1075</b>			
Drive .....	6146		6872
Trans. ....	8005		6872
<b>1076; 1077</b>			
Drive .....	6489		6878
<b>1100 Special</b>			
Drive; W/8-Speed Drive .....	7473		6982
<b>1116</b>			
Eng. To Deck .....	110420		6848
<b>1257; 1267</b>			
Drive .....	1586		6876
<b>1276; 1277</b>			
Drive .....	6489		6878
<b>2165</b>			
Deck .....	106516		A81
Trans. ....	108427		6463BR
<b>4178</b>			
Deck .....	1594		6781BR
Trans. ....	7473		6982
<b>78305</b>			
Drive .....	102741		6638BR
Spindle .....	8411	2770	
<b>78345</b>			
Drive .....	102742		6378
Spindle .....	6738		6886

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHEEL HORSE - Continued</b>			
<b>78350</b>			
Blade Drive .....	106125		6889
Eng. To Deck .....	108834		6898
<b>78355</b>			
Deck; W/89" Belt O.C. ....	106125		6889
Deck; W/98" Belt O.C. ....	108834		6898
<b>78360</b>			
Drive .....	102742		6378
Spindle .....	1594		6781BR
<b>78390</b>			
Drive .....	113072		A100
Spindle .....	112449		B128
<b>A50</b>			
Trans. ....	9430		6836
<b>A51; A81E; A81R</b>			
Belt .....	9430		6836
Trans. ....	9430		6836
<b>A85</b>			
Drive .....	113105		6833
<b>A111</b>			
Belt .....	9430		6836
Trans. ....	9430		6836
<b>A115</b>			
Drive .....	113105		6833
<b>B82; B112</b>			
Trans. ....	106518		6887
<b>B115; B165</b>			
Traction .....	108427		6463BR
<b>C85</b>			
Drive; W/8-Speed Drive .....	7473		6982
<b>C105</b>			
Drive; W/8-Speed Eng. ....	7473		6982
<b>C125; C145; C165</b>			
Drive; W/8-Speed Drive .....	7473		6982
Drive; W/Automatic Drive .....	7478		6984
<b>C175</b>			
Drive; W/82" Belt O.C. ....	7473		6982
Drive; W/83" Belt O.C. ....			6983
Eng. To Deck .....	102741		6638BR
<b>E81</b>			
Traction .....	104290	1293	
<b>GT1100</b>			
Drive; W/8-Speed Drive .....	7473		6982
<b>GT1142</b>			
Deck .....	6738		6886
Drive .....	7473		6982
<b>GT1600; GT1642</b>			
Drive .....			6983
<b>GT1848</b>			
Deck .....	1594		6781BR
<b>GT2500</b>			
Drive; W/8-Speed Drive .....	7473		6982
<b>L105; L106; L107; L155; L156; L157</b>			
Blade .....	1555		6844
Drive .....	1576		6870
Trans. ....	9691		6870
<b>LT1137</b>			
Traction .....	108427		6463BR
<b>RE67</b>			
Blade .....	1596		6851
Drive .....	1597		6725
Idler .....	6993		6822
<b>RM115; RM116</b>			
Belt .....	1555		6844



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHEEL HORSE - Continued</b>				<b>WHITE OUTDOOR PRODUCTS - Continued</b>			
<b>RM483; RM484; RM485</b>				<b>722 Thru 757</b>			
Blade Drive .....	1594		6781BR	Variator .....	7540248		6431BR
Main Drive .....	1595		6867				
<b>RR47; RR67</b>				<b>746</b>			
Blade .....	1596		6851	Drive .....	7540248		6431BR
Drive .....	1597		6725	Tiller Attachment .....	7540283		6895
Idler .....	6993		6822				
<b>RR532; RR832</b>				<b>776</b>			
Belt .....	9430		6836	Drive; W/37" Belt O.C. ....	7540255		6837
				Drive; W/59" Belt O.C. ....	7540245		6859
<b>SB371</b>				<b>782</b>			
Trans. ....	106518		6887	Blade .....	7540245		6859
				Trans. ....	7540255		6837
<b>WHEELER</b>				<b>802 Thru 827</b>			
<b>WES-725</b>				Deck .....	7540245		6859
Blade .....	30631		6942	Eng. To Transaxle .....	7540244		6840
<b>WHITE OUTDOOR PRODUCTS</b>				<b>822</b>			
<b>0042T-11</b>				Blade .....	7540245		6859
Deck .....	9003003A		6895	Trans. ....	7540244		6840
<b>134A606F190; 134A676F190</b>				<b>842</b>			
Blade .....	7540433		6630BR	Blade .....	7540245		6859
				Trans. ....	7540177		6832
<b>134B561B190</b>				<b>931</b>			
Blade .....	7540264		6639BR	Drive; W/56" Belt O.C. ....	7540230		6755BR
Drive .....	754-0241A		6494BR	Drive; W/69" Belt O.C. ....	7540260		5716
Trans. ....	7540240		6511BR				
<b>134R616G190</b>				<b>935</b>			
Drive .....	7540870		6947	Belt; W/44" Rear Discharge .....	7540230		6755BR
				Blade; W/56" Belt O.C. ....	7540230		6755BR
<b>144-822; 144-832 (GT1810)</b>				Blade; W/74 1/2" Belt O.C. ....	7540293		6501BR
Deck .....	7540245		6859	Drive .....	7540230		6755BR
Eng. To Transaxle .....	7540244		6840				
<b>144-994 (GT1655)</b>				<b>936</b>			
Eng. To Deck .....	7540230		6755BR	Blade .....	7540230		6755BR
Eng. To J.S. ....	7540245		6859				
J.S. ....	7540244		6840	<b>990-009(R80)</b>			
<b>317D</b>				Blade .....	7540200		6848
Blade; W/67" Belt O.C.; W/1/2" Belt				Trans. ....	7540178	3820	
T.W. ....	7540355		6448BR	<b>990-12(T-80)</b>			
Blade; W/67" Belt O.C.; W/5/8" Belt				Blade .....	32000997		6964
T.W. ....	7540151		6967	Drive .....	320009962	2630	6863
<b>336</b>				<b>990-012(T80)</b>			
Blade .....	7540342		6868	Blade .....	7540167		6964
				Trans. ....	7540198		6451BR
<b>511</b>				<b>990-013(T85)</b>			
Variator; W/35" Belt O.C. ....	7540241		6494BR	Blade .....	7540151		6967
Variator; W/38" Belt O.C. ....	7540240		6511BR	Eng. To Variator .....	7540138		6950
				Variator To Trans. ....	7540136		6931
<b>514</b>				<b>990-014(T100)</b>			
Blade .....	7540229		6852	Blade .....	7540145		6488BR
Deck .....	7540264		6639BR	Eng. To Variator .....	7540191		6865
Eng. To J.S.; W/30" Deck .....	7540241		6494BR	Variator To Trans. ....	7540173	3370	6937
J.S. To Trans.; W/30" Deck .....	7540240		6511BR	<b>990-027(GT1050); 990-028(GT1600)</b>			
<b>556; 666</b>				Gen. ....	7540169	7355	
Drive .....	7540349		6637BR	P.T.O. ....	7540165		6834
				Trans. ....	7540124	2570	6857
<b>686</b>				<b>990-029(GT1650)</b>			
Blade .....	7540293		6501BR	Gen. ....	7540169	7355	
				Trans. ....	7540124	2570	6857
<b>688</b>				<b>990-074(R50)</b>			
Blade; W/52" Belt O.C. ....	7540229		6852	Blade .....	7540188		6951
Blade; W/74" Belt O.C. ....	7540293		6501BR	Eng. To Variator .....	7540187	3240	6924
Deck .....	7540277		6871	Variator To Trans. ....	7540136		6931
<b>690</b>				<b>990-074(R-50)</b>			
Blade; W/52" Belt O.C. ....	7540229		6852	Blade .....	7540188		6951
Blade; W/74" Belt O.C. ....	7540293		6501BR	Trans. ....	7540136		6931
Deck; W/2-Blades .....	7540151		6967	Variable Speed .....	7540187	3240	
<b>704</b>				<b>990-075(T800)</b>			
Blade; W/52" Belt O.C. ....	7540229		6852	Blade .....	7540195		6854
Blade; W/74" Belt O.C. ....	7540293		6501BR	Trans. ....	7540198		6451BR
<b>708</b>				<b>990-076(GT1000); 990-077(GT1000)</b>			
Blade; W/38" Deck .....	7540145		6488BR	Blade .....	7540184		6852

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE OUTDOOR PRODUCTS - Continued</b>			
<b>990-076(GT1000); 990-077(GT1000) – Continued</b>			
Clutch .....	7540182		6981
Gear Box .....	7540180		6510BR
Gen. ....	7540134	7330	
<b>990-100(GT1050); 990-101(GT1600)</b>			
Gen. ....	7540169	7355	
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>990-103(GT1650)</b>			
Gen. ....	7540169	7355	
Trans. ....	7540124	2570	6857
<b>990-106(R50); 990-106(T-50)</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>990-116(T82)</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>990-117(T102)</b>			
Blade .....	7540145		6488BR
Eng. To Variator .....	7540191		6865
Variator To Trans. ....	7540173	3370	6937
<b>990-118(T802)</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>990-119(GT1020); 990-120(GT1620)</b>			
P.T.O. ....	7540210		6960
Transaxle .....	7540212		6945
<b>990-137(GT1622)</b>			
P.T.O. ....	7540227		6963
Trans. ....	7540212		6945
<b>990-139 (T112)</b>			
Blade .....	7540225		6565
Trans. ....	7540226		6551BR
<b>990-140(T110)</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>990-141(R82)</b>			
Blade .....	7540188		6951
Trans. ....	7540207		6842
<b>990-141(R-82)</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>991-106(R50); 991-106(R-50)</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>991-137(GT1622)</b>			
P.T.O. ....	7540227		6963
Trans. ....	7540212		6945
<b>991-183(R82); 991-183(R-82)</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>991-185(T82)</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>991-189(GT1655)</b>			
Deck .....	7540230		6755BR
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540255		6837
P.T.O. ....	7540234		6841
<b>991-248(T110)</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>991-249(T803)</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE OUTDOOR PRODUCTS - Continued</b>			
<b>991-250(1100)</b>			
Blade .....	7540250	2530	6853
Drive; W/38" Deck .....	7540214		6850
Trans. ....	7540248		6431BR
<b>991-251(1155); 991-252(1655)</b>			
Drive; W/38" Deck .....	7540214		6850
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540255		6837
<b>991-255(GT1822)</b>			
P.T.O. ....	7540227		6963
Trans. ....	7540212		6945
<b>991-256(GT1855)</b>			
P.T.O. ....	7540234		6841
<b>992-106(R50); 992-106(R-50)</b>			
Blade .....	7540188		6951
Trans. ....	7540101		6517BR
<b>992-141(R82)</b>			
Blade .....	7540188		6951
Trans. ....	7540207		6842
<b>992-183(R82); 992-183(R-82)</b>			
Blade .....	7540198		6451BR
Trans. ....	7540207		6842
<b>992-185(T82)</b>			
Blade .....	7540151		6967
Trans. ....	7540191		6865
<b>992-248(T-100)</b>			
Blade .....	7540145		6488BR
Trans. ....	7540198		6451BR
<b>992-248(T110)</b>			
Blade .....	7540145		6488BR
Trans. ....	7540226		6551BR
<b>992-249(T803)</b>			
Blade .....	7540195		6854
Trans. ....	7540198		6451BR
<b>992-250(LGT1100)</b>			
Blade .....	7540250	2530	6853
Drive; W/38" Deck .....	7540251		6809BR
Trans. ....	7540248		6431BR
<b>992-251(LGT1155); 992-252(LGT1655)</b>			
Blade .....	7540250	2530	6853
Drive; W/38" Deck .....	7540251		6809BR
Eng. To J.S. ....	7540245		6859
J.S. ....	7540255		6837
<b>992-255(GT1822)</b>			
P.T.O. ....	7540227		6963
Trans. ....	7540212		6945
<b>992-256(GT1855); 994-256 (GT1655)</b>			
P.T.O. ....	7540234		6841
<b>994-300 (LGT1655)</b>			
Blade .....	7540244		6840
<b>994-302 (GT1855)</b>			
P.T.O. ....	7540234		6841
<b>994-303 (GT1822)</b>			
Trans.; W/45" Belt O.C. ....	7540212		6945
Trans.; W/63" Belt O.C. ....	7540227		6963
<b>994-304 (GT1610)</b>			
Blade .....	7540245		6859
Trans. ....	7540244		6840
<b>994-306 (LGT1600)</b>			
Variable Speed .....	7540248		6431BR
<b>994-308 (LT110)</b>			
Blade; W/69" Belt O.C. ....	7540145		6488BR
Blade; W/85" Belt O.C. ....	7540266		6775BR
<b>995; 996</b>			
Drive .....	7540234		6841



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE OUTDOOR PRODUCTS - Continued</b>			
<b>998</b>			
Hydro. Traction .....	7540234		6841
<b>FR11</b>			
Eng. To Deck .....	9003004		6854
Trans. ....	9003011		6839
<b>FR-12</b>			
Trans. ....	9003011		6839
<b>FR18C</b>			
Eng. To Deck .....	9003004		6854
Trans. ....	9003011		6839
<b>FR-1800</b>			
Drive .....	9003011		6839
<b>FR-2000C</b>			
Blade .....	9003006		6853
<b>FR-2200D</b>			
Drive; W/62" Deck .....	9003020		6971
Drive; W/72" Deck .....	9003016		6984
<b>FR-2200G</b>			
Drive; W/62" Deck .....	9003021		6966
Drive; W/72" Deck .....	9003015		6981
<b>GT180</b>			
Eng. To Deck .....	7540350		6464BR
<b>GT185</b>			
Blade .....	7540349		6637BR
P.T.O. ....	7540350		6464BR
<b>GT205</b>			
Blade .....	7540291		6641BR
P.T.O. ....	7540364		6482BR
<b>GT1610</b>			
Eng. To Deck .....	7540230		6755BR
Eng. To J.S. ....	7540245		6859
J.S. ....	7540244		6840
<b>GT1845</b>			
Eng. To J.S. ....	7540229		6852
Tiller Attachment .....	7540283		6885
<b>GT2055</b>			
Blade .....	1469		B133
<b>L10 (425E)</b>			
Blade .....	7540364		6482BR
<b>L11 (847)</b>			
Drive .....	7540281		6405BR
<b>L12 (666F)</b>			
Drive .....	7540370		6439BR
<b>L145 (736G)</b>			
Drive .....	7540372		6881
<b>LGT160</b>			
Variator .....	7540248		6431BR
<b>LGT165 (826H)</b>			
Drive .....	7540365		6798BR
<b>LGT165 (836H)</b>			
Blade; W/64" Belt O.C. ....	7540350		6464BR
Blade; W/79" Belt O.C. ....	7540349		6637BR
Drive .....	7540365		6798BR
<b>LGT165/GT/180 (826H/846H)</b>			
Blade; W/64" Belt O.C. ....	7540350		6464BR
Blade; W/79" Belt O.C. ....	7540349		6637BR
<b>LGT1600 (Model 138-754)</b>			
Belt; W/46" Deck .....	7540350		6464BR
<b>LGT1655</b>			
Deck .....	7540230		6755BR
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540255		6837
<b>LT11</b>			
Eng. To Deck .....	7540342		6868

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE OUTDOOR PRODUCTS - Continued</b>			
<b>LT12 (133H471F)</b>			
Drive .....	7540281		6405BR
<b>LT12 (133K676F190)</b>			
Drive .....	7540370		6439BR
<b>LT12</b>			
Deck .....	7540329		6630BR
<b>LT14 (133R676G190)</b>			
Drive .....	7540370		6439BR
<b>LT84</b>			
Deck .....	7540151		6967
<b>LT110</b>			
Deck .....	7540145		6488BR
<b>LT120</b>			
Deck; W/64" Belt O.C. ....	7540350		6464BR
Deck; W/69 1/4" Belt O.C. ....	7540329		6630BR
<b>LT125 (606F)</b>			
Drive .....	7540349		6637BR
<b>LT125 (706F); LT125 (716F)</b>			
Drive .....	7540372		6881
<b>LT140</b>			
Deck .....	7540329		6630BR
<b>LT165; LT180</b>			
Blade .....	7540349		6637BR
Deck .....	7540350		6464BR
<b>R-10 (133B561B190B)</b>			
Blade .....	7540264		6639BR
Drive; W/35" Belt O.C. ....	7540241		6494BR
Drive; W/38" Belt O.C. ....	7540240		6511BR
<b>R-10 (521B)</b>			
Blade .....	7540264		6639BR
Drive .....	7540240		6511BR
<b>R-10 (521D)</b>			
Blade; W/47" Belt O.C. ....	7540290		6847
Blade; W/63" Belt O.C. ....	7540347		6847BR
<b>R53; R86</b>			
Deck; W/30" Deck .....	7540264		6639BR
Eng. To J.S.; W/30" Deck .....	7540241		6494BR
J.S. To Trans.; W/30" Deck .....	7540240		6511BR
<b>WHITE STORES</b>			
<b>86-121</b>			
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>86-123</b>			
P.T.O. ....	7540165		6834
<b>86-502; 86-515</b>			
Blade; W/25" Deck .....	7540138	3500	6950
Blade; W/30" Deck .....	7540167		6964
Trans. ....	7540164	2630	6863
<b>86-530</b>			
Deck .....	7540145		6488BR
Trans. ....	7540127		6966
Variable Speed .....	7540173	3370	6937
<b>87-75; 87-80</b>			
Trans. ....	7540112	3800	6980
<b>87-110</b>			
Blade .....	7540184		6852
Eng. To Deck .....	7540180		6510BR
Starter/Gen. ....	7540134	7330	
Trans.; W/80" Belt O.C. ....	7540112	3800	6980
Trans.; W/81" Belt O.C. ....	7540182	3810	6981
<b>87-112</b>			
J.S. ....	7540245		6859
Starter/Gen. ....	7540134	7330	
Trans. ....	7540244		6840

Lawn & Garden Equipment

# RIDING MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE STORES - Continued</b>			
<b>87-113</b>			
Trans. ....	7540182	3810	6981
<b>87-115</b>			
Starter/Gen.; W/33" Belt O.C. ....	7540134	7330	
Starter/Gen.; W/38" Belt O.C. ....	7540139	7380	
Trans.; W/57" Belt O.C. ....	7540124		6857
Trans.; W/81" Belt O.C. ....	7540182	3810	6981
<b>87-120</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>87-121</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540139	7380	
Trans. ....	7540124		6857
<b>87-122</b>			
P.T.O. ....	7540165		6834
<b>87-123</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540169	7355	
Trans. ....	7540124		6857
<b>87-125</b>			
P.T.O. ....	7540123		3V335
Trans. ....	7540124		6857
<b>87-400</b>			
Blade ....	7540188		6951
Trans. ....	7540101		6517BR
<b>87-402</b>			
Blade ....	7540147	3520	6952
Eng. To Variator ....	7540135		6925
Variator To Trans. ....	7540136		6931
<b>87-405</b>			
Blade ....	7540188		6951
Trans. ....	7540101		6517BR
<b>87-430</b>			
Blade ....	7540178	3820	6982
Trans. ....	7540185		6849
<b>87-440</b>			
Blade ....	7540198		6451BR
Trans. ....	7540207		6842
<b>87-502</b>			
Blade ....	7540935	2310	6831
Trans. ....	7540108	2460	6846
<b>87-515</b>			
Drive ....	7540164	2630	6863
<b>87-517</b>			
Blade ....	7540195		6854
Trans. ....	7540198		6451BR
<b>87-520</b>			
Blade ....	7540151		6967
Eng. To Variator ....	7540138	3500	6950
Variator To Trans. ....	7540136		6931
<b>87-521</b>			
Blade ....	7540151		6967
Trans. ....	7540191		6865
<b>87-524; 87-525</b>			
Blade ....	7540151		6967
Eng. To Variator ....	7540138	3500	6950
Variator To Trans. ....	7540136		6931
<b>87-530</b>			
Blade ....	7540145		6488BR
Drive ....	7540173	3370	6937
Eng. To Variator ....	7540191		6865
Trans. ....	7540127		6966
<b>87-540</b>			
Blade ....	7540145		6488BR
Trans. ....	7540266		6775BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE STORES - Continued</b>			
<b>87-5105</b>			
Blade ....	7540249		6930
Trans. ....	7540264		6639BR
<b>87-5108</b>			
Variator; W/35" Belt O.C. ....	7540241		6494BR
Variator; W/38" Belt O.C. ....	7540240		6511BR
<b>87-5211</b>			
Blade ....	7540145		6488BR
Trans. ....	7540266		6775BR
<b>130-340</b>			
Blade ....	7540107		6830
Trans. ....	7540936		6847
<b>130-410</b>			
Blade ....	7540138	3500	6950
Trans. ....	7540101		6517BR
<b>130-420</b>			
Blade ....	7540127		6966
Eng. To Variator ....	7540135		6925
Variator To Trans. ....	7540136		6931
<b>130-460</b>			
Blade ....	7540118		6963
Trans. ....	7540937	3590	6959
<b>132-390</b>			
Blade; W/25" Deck ....	7540138	3500	6950
Blade; W/30" Deck ....	7540167		6964
Trans. ....	7540164	2630	6863
<b>132-418</b>			
Blade ....	7540147	3520	6952
Eng. To Variator ....	7540135		6925
Variator To Trans. ....	7540136		6931
<b>132-485</b>			
Blade ....	7540151		6967
Eng. To Variator ....	7540138	3500	6950
Variator To Trans. ....	7540136		6931
<b>133-380</b>			
Blade ....	7540138	3500	6950
Trans. ....	7540164	2630	6863
<b>133-390</b>			
Blade ....	7540167		6964
Trans. ....	7540164	2630	6863
<b>133-420</b>			
Blade ....	7540147	3520	6952
Eng. To Variator ....	7540135		6925
Variator To Trans. ....	7540136		6931
<b>133-445</b>			
Blade ....	7540178	3820	6982
Trans. ....	7540179		6950
<b>133-495</b>			
Blade ....	7540145		6488BR
Trans. ....	7540127		6966
<b>134-380</b>			
Blade ....	7540138	3500	6950
Trans. ....	7540164	2630	6863
<b>134-390</b>			
Blade ....	7540167		6964
Trans. ....	7540164	2630	6863
<b>134-445</b>			
Blade ....	7540178	3820	6982
Trans. ....	7540185		6849
<b>134-465</b>			
Blade ....	7540151		6967
Eng. To Variator ....	7540138	3500	6950
Variator To Trans. ....	7540136		6931
<b>134-495</b>			
Blade ....	7540145		6488BR
Eng. To J.S. ....	7540191		6865
J.S. To Trans. ....	7540173	3370	6937





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE STORES - Continued</b>			
<b>135-330</b>			
Trans. ....	7540239	2290	6829
<b>135-340</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540936		6847
<b>135-380</b>			
Blade .....	7540935	2310	6831
Trans. ....	7540108	2460	6846
<b>136-501</b>			
Variator .....	7540240		6511BR
<b>136-514</b>			
Variator .....	7540241		6494BR
<b>140-660; 142-669</b>			
Starter/Gen. ....	7540134	7330	
Trans. ....	7540112	3800	6980
<b>142-760; 142-960</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540139	7380	
Trans. ....	7540124		6857
<b>142-990</b>			
P.T.O. ....	7540165		6834
<b>143-660</b>			
Blade .....	7540184		6852
Eng. To Deck .....	7540180		6510BR
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>143-760</b>			
Starter/Gen. ....	7540134	7330	
Trans. ....	7540182	3810	6981
<b>143-960</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540139	7380	
Trans. ....	7540124		6857
<b>143-990</b>			
P.T.O. ....	7540165		6834
Starter/Gen. ....	7540169	7355	
Trans. ....	7540124		6857
<b>144-672</b>			
Blade .....	7540184		6852
Eng. To Deck .....	7540180		6510BR
Trans. ....	7540182	3810	6981
<b>144-918</b>			
P.T.O. ....	7540227		6963
Trans. ....	7540212		6945
<b>144-960; 144-990</b>			
P.T.O. ....	7540165		6834
Trans. ....	7540124		6857
<b>511; 514</b>			
Variator; W/35" Belt O.C. ....	7540241		6494BR
Variator; W/38" Belt O.C. ....	7540240		6511BR
<b>WOODS</b>			
<b>1855</b>			
Eng. To J.S. ....	381914		AX34
<b>1860</b>			
Eng. To J.S.; W/Kubota D600 Eng. ....	381914		AX34
Fan & Alt.; W/Kubota D600 Eng. ....	REMF1320	7320	
<b>2150</b>			
Eng. To J.S. ....	381914		AX34
<b>6160; 6182; 6210</b>			
P.T.O. ....	70341		AX34
<b>6215; 6250</b>			
Fan .....		7343	
P.T.O. ....	70341		AX34
<b>V23</b>			
Drive .....	35582		6828

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WOODS - Continued</b>			
<b>V42</b>			
Belt; W/CM36 Deck .....	35583		6851
<b>WORLDLAWN POWER EQUIPMENT</b>			
<b>WYK52FX730V5</b>			
Deck Drive .....	543097		6878BR
Pump Drive .....	543005		7046BR
<b>WYK60FX801V5</b>			
Deck Drive .....	543103		6880BR
Pump Drive .....	543005		7046BR
<b>WYRZ46S20BS</b>			
Pump Drive .....	5002004		7038BR
<b>WYRZ50U24KW; WYRZ50U26BS</b>			
Deck Drive .....	5001002		6692BR
Pump Drive .....	5002004		7038BR
<b>WYS52FX730V</b>			
Eng. To Deck .....	453214		6865BR
Pump Drive .....	453311		7005BR
<b>WYZ34FS600V</b>			
Deck Drive .....	353111		6715BR
Pump Drive .....	353112		6986BR
<b>WYZ4824KWH</b>			
Deck Drive .....	4821002		6787BR
Pump Drive .....	5207016		6819BR
<b>WYZ5224KWH; WYZ5227KWH</b>			
Deck Drive .....	5201008		6732BR
Pump Drive .....	5207016		6819BR
<b>WYZ6024KWH; WYZ6027KWH</b>			
Deck Drive .....	6001001		6853BR
Pump Drive .....	5207016		6819BR
<b>WRIGHT MANUFACTURING, INC.</b>			
<b>WS3215KAW; WS3216KAW; WS3217KAWRE; WS3218KAWRE</b>			
Deck Drive .....	71460063		6838BR
Hydro. ....	71460033		6819BR
<b>WS3615KAW; WS3616KAW; WS3617KAWRE; WS3618KAWRE</b>			
Deck Drive .....	71460062		6675BR
Hydro. ....	71460033		6819BR
<b>WS4217KAWRE; WS4218KAWRE</b>			
Deck Drive .....	71460013		6839BR
Hydro. ....	71460033		6819BR
<b>WS4817KAW; WS4817KAWRE; WS4818KAWRE</b>			
Blade To Blade .....	71460070		6822BR
Eng. To Deck .....	71460074		6644BR
Hydro. ....	71460033		6819BR
<b>WS4819KAWRE; WS4820KAWRE</b>			
Blade To Blade .....	71460070		6822BR
Eng. To Deck .....	71460123		6840BR
Hydro. ....	71460064		6837BR
<b>WS4823KAWRE</b>			
Blade Drive .....	71460070		6822BR
Eng. To Deck .....	71460123		6840BR
Hydro. ....	71460064		6837BR
<b>WS4824KAWRE</b>			
Blade To Blade .....	71460070		6822BR
Eng. To Deck .....	71460123		6840BR
Hydro. ....	71460064		6837BR
<b>WS5217KAWRE; WS5219KAWRE</b>			
Blade To Blade; Ser. No. 49704 & Before .....	71460002		6564BR
Blade To Blade; Ser. No. 49705 & After .....	71460065		6823BR
Eng. To Deck; Ser. No. 49704 & Before .....	71460003		6815BR
Eng. To Deck; Ser. No. 49705 & After ....	71460107		6866BR
Hydro.; Ser. No. 49704 & Before .....	71460033		6819BR
Hydro.; Ser. No. 49705 & After .....	71460064		6837BR

Lawn & Garden Equipment

**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WRIGHT MANUFACTURING, INC. - Continued</b>			
<b>WS5220KAW</b>			
Blade Drive .....	71460065		<b>6823BR</b>
Eng. To Deck .....	71460107		<b>6866BR</b>
Hydro. Drive .....	71460064		<b>6837BR</b>
<b>WS5223KAW</b>			
Blade To Blade; Ser. No. 49704 & Before .....	71460002		<b>6564BR</b>
Blade To Blade; Ser. No. 49705 & After ..	71460065		<b>6823BR</b>
Eng. To Deck; Ser. No. 49704 & Before ..	71460003		<b>6815BR</b>
Eng. To Deck; Ser. No. 49705 & After ....	71460107		<b>6866BR</b>
Hydro.; Ser. No. 49704 & Before .....	71460033		<b>6819BR</b>
Hydro.; Ser. No. 49705 & After .....	71460064		<b>6837BR</b>
<b>WS5223KCE</b>			
Blade To Blade .....	71460002		<b>6564BR</b>
Eng. To Deck .....	71460003		<b>6815BR</b>
Hydro. ....	71460033		<b>6819BR</b>
<b>WS5224KAW</b>			
Blade Drive .....	71460065		<b>6823BR</b>
Eng. To Deck .....	71460107		<b>6866BR</b>
Hydro. Drive .....	71460064		<b>6837BR</b>
<b>WS5225KAW</b>			
Blade To Blade; Ser. No. 49704 & Before .....	71460002		<b>6564BR</b>
Blade To Blade; Ser. No. 49705 & After ..	71460065		<b>6823BR</b>
Eng. To Deck; Ser. No. 49704 & Before ..	71460003		<b>6815BR</b>
Eng. To Deck; Ser. No. 49705 & After ....	71460107		<b>6866BR</b>
Hydro.; Ser. No. 49704 & Before .....	71460033		<b>6819BR</b>
Hydro.; Ser. No. 49705 & After .....	71460064		<b>6837BR</b>
<b>WS5226KAW</b>			
Blade Drive .....	71460065		<b>6823BR</b>
Eng. To Deck .....	71460107		<b>6866BR</b>
Hydro. Drive .....	71460064		<b>6837BR</b>
<b>WS6123KAW</b>			
Blade To Blade; Ser. No. 49704 & Before .....	71460012		<b>6854BR</b>
Blade To Blade; Ser. No. 49705 & After ..	71460067		<b>6855BR</b>
Eng. To Deck; Ser. No. 49704 & Before ..	71460013		<b>6839BR</b>
Eng. To Deck; Ser. No. 49705 & After ....	71460071		<b>6856BR</b>
Hydro.; Ser. No. 49704 & Before .....	71460033		<b>6819BR</b>
Hydro.; Ser. No. 49705 & After .....	71460064		<b>6837BR</b>
<b>WS6123KCE</b>			
Blade To Blade .....	71460013		<b>6839BR</b>
Eng. To Deck .....	71460012		<b>6854BR</b>
Hydro. ....	71460033		<b>6819BR</b>
<b>WS6124KAW</b>			
Blade Drive .....	71460067		<b>6855BR</b>
Eng. To Deck .....	71460071		<b>6856BR</b>
Hydro. Drive .....	71460064		<b>6837BR</b>
<b>WS6125KAW</b>			
Blade To Blade; Ser. No. 49704 & Before .....	71460012		<b>6854BR</b>
Blade To Blade; Ser. No. 49705 & After ..	71460067		<b>6855BR</b>
Eng. To Deck; Ser. No. 49704 & Before ..	71460013		<b>6839BR</b>
Eng. To Deck; Ser. No. 49705 & After ....	71460071		<b>6856BR</b>
Hydro.; Ser. No. 49704 & Before .....	71460033		<b>6819BR</b>
Hydro.; Ser. No. 49705 & After .....	71460064		<b>6837BR</b>
<b>WS6126KAW</b>			
Blade Drive .....	71460067		<b>6855BR</b>
Eng. To Deck .....	71460071		<b>6856BR</b>
Hydro. Drive .....	71460064		<b>6837BR</b>
<b>WSE4819KAW; WSE4823KAW</b>			
Blade To Blade; Ser. No. 26980 & After ..	71460070		<b>6822BR</b>
Deck Drive; Ser. No. 26979 & Before ....	71460040		<b>6857BR</b>
Eng. To Deck; Ser. No. 26980 & After ....	71460063		<b>6838BR</b>
Hydro.; Ser. No. 26979 & Before .....	71460041		<b>6685BR</b>
Hydro.; Ser. No. 26980 & After .....	71460064		<b>6837BR</b>
<b>WSE4823KCE</b>			
Deck .....	71460040		<b>6857BR</b>
Hydro. ....	71460041		<b>6685BR</b>

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WRIGHT MANUFACTURING, INC. - Continued</b>			
<b>WSE5223KAW</b>			
Blade To Blade; Ser. No. 26980 & After ..	71460065		<b>6823BR</b>
Deck Drive; Ser. No. 26979 & Before ....	71460035		<b>6858BR</b>
Eng. To Deck; Ser. No. 26980 & After ....	71460062		<b>6675BR</b>
Hydro.; Ser. No. 26979 & Before .....	71460041		<b>6685BR</b>
Hydro.; Ser. No. 26980 & After .....	71460064		<b>6837BR</b>
<b>WSE5223KCE</b>			
Deck .....	71460035		<b>6858BR</b>
Hydro. ....	71460041		<b>6685BR</b>
<b>WSE5225KAW</b>			
Blade To Blade; Ser. No. 26980 & After ..	71460065		<b>6823BR</b>
Deck Drive; Ser. No. 26979 & Before ....	71460035		<b>6858BR</b>
Eng. To Deck; Ser. No. 26980 & After ....	71460062		<b>6675BR</b>
Hydro.; Ser. No. 26979 & Before .....	71460041		<b>6685BR</b>
Hydro.; Ser. No. 26980 & After .....	71460064		<b>6837BR</b>
<b>WSE5225KCE</b>			
Deck .....	71460035		<b>6858BR</b>
Hydro. ....	71460041		<b>6685BR</b>
<b>WSE6123KAW</b>			
Blade To Blade; Ser. No. 26980 & After ..	71460067		<b>6855BR</b>
Deck Drive; Ser. No. 26979 & Before ....	71460036		<b>6589BR</b>
Eng. To Deck; Ser. No. 26980 & After ....	71460013		<b>6839BR</b>
Hydro.; Ser. No. 26979 & Before .....	71460041		<b>6685BR</b>
Hydro.; Ser. No. 26980 & After .....	71460064		<b>6837BR</b>
<b>WSE6123KCE</b>			
Deck .....	71460036		<b>6589BR</b>
Hydro. ....	71460041		<b>6685BR</b>
<b>WSE6125KAW</b>			
Blade To Blade; Ser. No. 26980 & After ..	71460067		<b>6855BR</b>
Deck Drive; Ser. No. 26979 & Before ....	71460036		<b>6589BR</b>
Eng. To Deck; Ser. No. 26980 & After ....	71460013		<b>6839BR</b>
Hydro.; Ser. No. 26979 & Before .....	71460041		<b>6685BR</b>
Hydro.; Ser. No. 26980 & After .....	71460064		<b>6837BR</b>
<b>WSE6125KCE</b>			
Deck .....	71460036		<b>6589BR</b>
Hydro. ....	71460041		<b>6685BR</b>
<b>WSES3617KAW; WSES3618KAWRE; WSES3619KAW; WSES3620KAW</b>			
Deck Drive .....	71460063		<b>6838BR</b>
Hydro. ....	71460066		<b>6820BR</b>
<b>WSES4217KAW; WSES4218KAWRE; WSES4219KAW; WSES4220KAW</b>			
Deck Drive .....	71460013		<b>6839BR</b>
Hydro. ....	71460066		<b>6820BR</b>
<b>WSES4819KAW; WSES4820KAW; WSES4823KAW; WSES4825KAW</b>			
Blade Drive .....	71460070		<b>6822BR</b>
Eng. To Deck .....	71460063		<b>6838BR</b>
Hydro. ....	71460066		<b>6820BR</b>
<b>WSES5219KAW; WSES5220KAW; WSES5223KAW; WSES5225KAW</b>			
Blade Drive .....	71460065		<b>6823BR</b>
Eng. To Deck .....	71460062		<b>6675BR</b>
Hydro. ....	71460066		<b>6820BR</b>
<b>WSPX4824KAW</b>			
Blade Drive .....	71460070		<b>6822BR</b>
Eng. To Deck .....	71460123		<b>6840BR</b>
Hydro. Drive .....	71460064		<b>6837BR</b>
<b>WSPX5224KAW</b>			
Blade Drive .....	71460065		<b>6823BR</b>
Eng. To Deck .....	71460107		<b>6866BR</b>
Hydro. Drive .....	71460064		<b>6837BR</b>
<b>WSPX6126KAW</b>			
Blade Drive .....	71460067		<b>6855BR</b>
Eng. To Deck .....	71460071		<b>6856BR</b>
Hydro. Drive .....	71460064		<b>6837BR</b>



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WRIGHT MANUFACTURING, INC. - Continued</b>			
<b>WSR3617KAWE; WSR3618KAWRE; WSR3619KAWE; WSR3620KAWE</b>			
Deck Drive .....	71460063		6838BR
Hydro .....	71460066		6820BR
<b>WSR4217KAWE; WSR4218KAWRE; WSR4219KAWE; WSR4220KAWE</b>			
Deck Drive .....	71460013		6839BR
Hydro .....	71460066		6820BR
<b>WSR4819KAWE; WSR4820KAWE; WSR4823KAWE; WSR4825KAWE</b>			
Blade Drive .....	71460070		6822BR
Eng. To Deck .....	71460063		6838BR
Hydro .....	71460066		6820BR
<b>WSR5219KAWE; WSR5220KAWE; WSR5223KAWE; WSR5225KAWE</b>			
Blade Drive .....	71460065		6823BR
Eng. To Deck .....	71460062		6675BR
Hydro .....	71460066		6820BR
<b>WSTX4824KAWE</b>			
Blade Drive .....	71460070		6822BR
Eng. To Deck .....	71460123		6840BR
Hydro .....	71460064		6837BR
<b>WSTX5224KAWE</b>			
Blade Drive .....	71460065		6823BR
Eng. To Deck .....	71460107		6866BR
Hydro .....	71460064		6837BR
<b>WSTX6126KAWE</b>			
Blade Drive .....	71460067		6855BR
Eng. To Deck .....	71460071		6856BR
Hydro .....	71460064		6837BR
<b>WSZK5227KAWE; WSZK5231KAWE</b>			
Blade Drive .....	71460065		6823BR
<b>WSZK6131KAWE</b>			
Blade Drive .....	71460067		6855BR
Eng. To Deck .....	71460040		6857BR
<b>WZ4821KAWE; WZ4823KAWE; WZ4827KAWE</b>			
Blade Drive .....	71460070		6822BR
Blower .....	71460099		6711BR
Hydro .....	71460074		6644BR
<b>WZ5223KAWE; WZ5225KAWE; WZ5227KAWE; WZ5231KAWE</b>			
Blade Drive .....	71460065		6823BR
Blower .....	71460099		6711BR
Eng. To Deck .....	71460085		6946BR
Hydro .....	71460074		6644BR
<b>WZ6125KAWE; WZ6127KAWE; WZ6131KAWE</b>			
Blade Drive .....	71460067		6855BR
Blower .....	71460099		6711BR
Hydro .....	71460074		6644BR
<b>YAMAHA</b>			
<b>YT3600</b>			
Blade .....			6965
Deck .....	LB109		B106
<b>YT6700</b>			
Belt; W/68" Deck .....			6968
<b>YT6800</b>			
Belt; W/48" Deck .....			6966
Belt; W/68" Deck .....			6968
Blade .....	LB103		B100
Trans.; W/48" Deck .....	LA85		6885
<b>YANMAR</b>			
<b>GT14</b>			
Fan & Alt .....	121023	9335	9335HD
<b>Mid-Deck</b>			
Belt; W/98" Belt O.C. ....			6998

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YANMAR - Continued</b>			
<b>YMR60 Mower</b>			
Belt .....			6974
<b>YARD MACHINES</b>			
<b>13A1660F000</b>			
Deck Drive .....	7540329A		6630BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	75404002		6618BR
<b>13A1760F700; 13A1762F029; 13A1762F229; 13A1762F700; 13A1762F729; 13A3760F700; 13A3762F700</b>			
Deck .....	754-04062		6774BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	754-0241A		6494BR
<b>13A3791G700</b>			
Deck .....	754-04060B		6776BR
Drive .....	75404074A		6414BR
<b>13A6665H</b>			
Cross Deck .....	7540440		6477BR
Eng. ....	7540280		6447BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540370		6439BR
<b>13A6695H</b>			
Cross Deck .....	7540440		6477BR
Drive .....	7540349		6637BR
Eng. To Deck .....	7540439		6406BR
<b>13AB560B</b>			
Deck .....	7540264		6639BR
Eng. ....	7540241		6494BR
Trans. ....	7540240		6511BR
<b>13AC560B</b>			
Deck .....	7540264		6639BR
Eng. ....	754-0241A		6494BR
Trans. ....	7540240		6511BR
<b>13AC650F700</b>			
Deck Drive .....	7540329A		6630BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	75404002		6618BR
<b>13AC762F000</b>			
Deck .....	754-04062		6774BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	754-0241A		6494BR
<b>13AC762F020</b>			
Deck Drive .....	954-04062		6774BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-0241A		6494BR
<b>13AC762F729</b>			
Deck .....	754-04062		6774BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	754-0241A		6494BR
<b>13AE451F</b>			
Deck .....	7540329A		6630BR
Eng. ....	7540280		6447BR
Trans. ....	7540281		6405BR
<b>13AF685G700; 13AF688G722</b>			
Deck Drive .....	7540371A		6402BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	75404002		6618BR
<b>13AF695G700; 13AF698G722</b>			
Deck Drive .....	7540371A		6402BR
Drive .....	7540338		6877
<b>13AG688H722</b>			
Deck Drive .....	7540440		6477BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	75404002		6618BR
Eng. To Deck .....	7540439		6406BR
<b>13AG695G</b>			
Deck .....	7540371A		6402BR
Fan .....	7540441		6417BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD MACHINES - Continued</b>			
<b>13AH660F</b>			
Eng. To Deck .....	7540329A		<b>6630BR</b>
Eng. To V.S. ....	7540280A		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>13AH661F</b>			
Eng. To Deck .....	7540329A		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>13AH762F752</b>			
Deck .....	754-04062		<b>6774BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	754-0241A		<b>6494BR</b>
<b>13AL450C</b>			
Deck .....	7540445		<b>6563BR</b>
Eng. ....	7540280		<b>6447BR</b>
Trans. ....	7540281		<b>6405BR</b>
<b>13AL660F</b>			
Eng. To Deck .....	7540329A		<b>6630BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>13AM475F</b>			
Deck .....	7540329A		<b>6630BR</b>
Eng. ....	7540280		<b>6447BR</b>
Trans. ....	7540281		<b>6405BR</b>
<b>13AM660F700</b>			
Deck Drive; W/38" Deck .....	7540329A		<b>6630BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	75404002		<b>6618BR</b>
<b>13AM660G</b>			
Eng. To Deck .....	7540371A		<b>6402BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>13AM675G</b>			
Eng. To Deck .....	9540371A		<b>6402BR</b>
Eng. To V.S. ....	9540280A		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>13AM685G000</b>			
Deck Drive .....	7540371A		<b>6402BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	75404002		<b>6618BR</b>
<b>13AM762F052</b>			
Deck .....	754-04062		<b>6774BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	754-0241A		<b>6494BR</b>
<b>13AM762G752</b>			
Deck .....	754-04060B		<b>6776BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	754-0241A		<b>6494BR</b>
<b>13AM772F000; 13AM772F700</b>			
Deck .....	754-04062		<b>6774BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	754-0241A		<b>6494BR</b>
<b>13AM772S000</b>			
Deck Drive .....	954-04060B		<b>6776BR</b>
Drive - Lower .....	954-04249A		<b>6520BR</b>
Drive - Upper .....	954-0241A		<b>6494BR</b>
<b>13AM6660G700</b>			
Deck Drive .....	7540371A		<b>6402BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	75404002		<b>6618BR</b>
<b>13AN475F</b>			
Deck .....	7540329A		<b>6630BR</b>
Eng. ....	7540280		<b>6447BR</b>
Trans. ....	7540281		<b>6405BR</b>
<b>13AN665G000</b>			
Deck Drive .....	7540371A		<b>6402BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	75404002		<b>6618BR</b>

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD MACHINES - Continued</b>			
<b>13AN695G</b>			
Deck .....	7540371A		<b>6402BR</b>
Fan .....	7540441		<b>6417BR</b>
<b>13AN771G729; 13AN771G731</b>			
Deck .....	754-04060B		<b>6776BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	754-0241A		<b>6494BR</b>
<b>13AN771H729</b>			
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	754-0241A		<b>6494BR</b>
Eng. To Deck .....	75404142		<b>6524BR</b>
Spindle .....	7540349		<b>6637BR</b>
<b>13AN772G000; 13AN772G029; 13AN772G229; 13AN772G700; 13AN772G729</b>			
Deck .....	754-04060B		<b>6776BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	754-0241A		<b>6494BR</b>
<b>13AQ607H</b>			
Cross Deck .....	7540349		<b>6637BR</b>
Drive .....	7540468		<b>6556BR</b>
P.T.O.; W/Electric P.T.O. ....	7540474		<b>6480BR</b>
P.T.O.; W/Man. P.T.O. ....	7540486		<b>6502BR</b>
Variable Speed .....	7540467		<b>6606BR</b>
<b>13AQ665H</b>			
Cross Deck .....	7540440		<b>6477BR</b>
Eng. To Deck .....	7540439		<b>6406BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540370		<b>6439BR</b>
<b>13BC762F000</b>			
Deck Drive .....	954-04062		<b>6774BR</b>
Drive - Lower .....	954-04249A		<b>6520BR</b>
Drive - Upper .....	954-0241A		<b>6494BR</b>
<b>13BN771G729</b>			
Deck .....	754-04060B		<b>6776BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	754-0241A		<b>6494BR</b>
<b>13BQ607H000</b>			
Deck Drive .....	7540349		<b>6637BR</b>
Drive - Lower .....	7540467		<b>6606BR</b>
Drive - Upper .....	7540468		<b>6556BR</b>
<b>13CH660F000</b>			
Deck Drive .....	7540329A		<b>6630BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	75404002		<b>6618BR</b>
<b>13RN772G029; 13RN772G229; 13RN772G729</b>			
Deck .....	754-04060B		<b>6776BR</b>
Drive - Lower .....	75404001A		<b>6969</b>
Drive - Upper .....	754-0241A		<b>6494BR</b>
<b>14AJ825P</b>			
Cross Deck .....	7540291A		<b>6641BR</b>
Eng. To Deck .....	7540364		<b>6482BR</b>
Eng. To V.S. ....	7540280		<b>6447BR</b>
V.S. To Trans. ....	7540446		<b>6605BR</b>
<b>14AS83AH</b>			
Cross Deck .....	7540349		<b>6637BR</b>
Drive .....	7540461		<b>6519BR</b>
Eng. ....	7540350		<b>6464BR</b>
<b>14AS825H</b>			
Cross Deck .....	7540349		<b>6637BR</b>
Deck .....	7540350		<b>6464BR</b>
Drive .....	7540280		<b>6447BR</b>
Trans. ....	7540446		<b>6605BR</b>
<b>YARD-MAN</b>			
<b>13A278SS501</b>			
Deck Drive .....	954-04060C		<b>6776BR</b>
Drive - Lower .....	954-0467A		<b>6606BR</b>
Drive - Upper .....	954-04208A		<b>7051BR</b>
<b>13A879ST501</b>			
Deck Drive .....	95404219		<b>6651BR</b>





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD-MAN - Continued</b>			
<b>13A879ST501 – Continued</b>			
Drive .....	95404252		6884
<b>13AC76LF055</b>			
Deck Drive .....	954-04062		6774BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-04265		6934
<b>13AC762F755</b>			
Deck Drive .....	754-04062		6774BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	754-0241A		6494BR
<b>13AD674G; 13AI674G</b>			
Deck .....	7540371A		6402BR
<b>13AJ694H</b>			
Cross Deck .....	7540440		6477BR
Eng. To Deck .....	7540439		6406BR
Trans. ....	7540441		6417BR
<b>13AM772G755</b>			
Deck Drive .....	754-04060B		6776BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	754-0241A		6494BR
<b>13AM772S055</b>			
Deck Drive .....	954-04060B		6776BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-0241A		6494BR
<b>13AN771G755</b>			
Deck .....	754-04060B		6776BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	754-0241A		6494BR
<b>13AN791G755</b>			
Deck .....	754-04060B		6776BR
Drive .....	75404074A		6414BR
<b>13AN795S001</b>			
Deck Drive .....	954-04060B		6776BR
Drive .....	95404252		6884
<b>13AO771H055</b>			
Deck Drive .....	7540349		6637BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	754-0241A		6494BR
Eng. To Deck .....	75404142		6524BR
<b>13AO772G055</b>			
Deck .....	754-04060B		6776BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	754-0241A		6494BR
<b>13AO772H755</b>			
Deck Drive .....	7540349		6637BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	754-0241A		6494BR
Eng. To Deck .....	75404142		6524BR
<b>13AO772S055</b>			
Deck Drive .....	954-04060B		6776BR
Drive - Lower .....	954-04249A		6520BR
Drive - Upper .....	954-0241A		6494BR
<b>13AO785T055</b>			
Deck Drive .....	95404219		6651BR
Drive - Lower .....	954-0467A		6606BR
Drive - Upper .....	95404208		7051BR
<b>13AP605H755</b>			
Deck Drive .....	75404118		6777BR
Drive - Lower .....	7540467		6606BR
Drive - Upper .....	7540468		6556BR
<b>13AP615P755</b>			
Deck Drive .....	75404048		6946BR
Drive .....	7540461		6519BR
<b>13AT79ST501</b>			
Deck Drive .....	95404219		6651BR
Drive .....	95404252		6884
<b>13AT604G701</b>			
Deck Drive .....	7540498		6448BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD-MAN - Continued</b>			
<b>13AT604G701 – Continued</b>			
Drive - Lower .....	7540467		6606BR
Drive - Upper .....	7540468		6556BR
<b>13AT604H701</b>			
Deck Drive .....	7540349		6637BR
Drive - Lower .....	7540467		6606BR
Drive - Upper .....	7540468		6556BR
<b>13AT605G755</b>			
Deck Drive .....	754-04060B		6776BR
Drive - Lower .....	7540467		6606BR
Drive - Upper .....	7540468		6556BR
<b>13AT605H755</b>			
Deck Drive .....	7540349		6637BR
Drive - Lower .....	7540467		6606BR
Drive - Upper .....	7540468		6556BR
<b>13AU615P755</b>			
Deck Drive .....	75404048		6946BR
Drive .....	7540461		6519BR
<b>13AX90YT001</b>			
Deck Drive .....	95404219		6651BR
Drive - Lower .....	95404267		6820BR
Drive - Upper .....	95404208		7051BR
<b>13AX605G755</b>			
Deck Drive .....	75404045		6663BR
Drive - Lower .....	7540467		6606BR
Drive - Upper .....	7540468		6556BR
<b>13AX615G055</b>			
Drive .....	75404165		6519BR
Spindle; W/42" Deck .....	75404045		6663BR
<b>13AX694G</b>			
Deck .....	7540371A		6402BR
Drive; 1997 .....	7540441		6417BR
Drive; 1998 .....	7540349		6637BR
<b>13AX694G401</b>			
Drive .....	7540441		6417BR
P.T.O. ....	7540371A		6402BR
<b>13BP605H755</b>			
Deck Drive .....	7540349		6637BR
Drive - Lower .....	7540467		6606BR
Drive - Upper .....	7540468		6556BR
Eng. To Deck .....	75404122		6713BR
<b>13BX605G755</b>			
Drive - Lower .....	7540467		6606BR
Drive - Upper .....	7540468		6556BR
Spindle; W/42" Deck .....	75404045		6663BR
<b>13RN772G055</b>			
Deck .....	754-04060B		6776BR
Drive - Lower .....	75404001A		6969
Drive - Upper .....	754-0241A		6494BR
<b>14AU844H</b>			
Drive .....	7540446		6605BR
Eng. ....	7540350		6464BR
Trans. ....	7540349		6637BR
<b>14AW834H</b>			
Cross Deck .....	7540349		6637BR
Drive .....	7540461		6519BR
Eng. ....	7540350		6464BR
<b>17AC2ACG055; 17AC2ACS055</b>			
Deck Drive .....	954-04137A		6684BR
Trans. ....	95404043A	2580	
<b>17AF2ACP001</b>			
Deck Drive .....	954-04044A		6842BR
Trans. ....	95404043A	2580	
<b>42"</b>			
Drive; W/15 H.P. Eng.; Hydro. Model .....	7540441		6417BR
Drive; W/18 H.P. Eng.; Hydro. Model .....	7540441		6417BR
P.T.O.; W/15 H.P. Eng.; Hydro. Model ...	7540371A		6402BR
P.T.O.; W/15 H.P. Eng.; W/7-Speed			
Drive .....	7540371A		6402BR

Lawn & Garden Equipment



**RIDING MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD-MAN - Continued</b>			
<b>42" - Continued</b>			
P.T.O.; W/18 H.P. Eng.; Hydro. Model ...	7540371A		6402BR
<b>46" Cut Hydro</b>			
Blade; W/22 H.P. Eng. ....	7540349		6637BR
P.T.O.; W/22 H.P. Eng. ....	7540350		6464BR
<b>50" Cut 14 Speed Hi-Lo Trans.</b>			
Blade; W/22 H.P. Eng. ....	7540291		6641BR
P.T.O. To Deck; W/22 H.P. Eng. ....	7540364		6482BR
<b>50" Cut Hydro</b>			
Blade; W/22 H.P. Eng. ....	7540291		6641BR
Drive; W/22 H.P. Eng. ....	7540349		6637BR
P.T.O. To Deck; W/22 H.P. Eng. ....	7540364		6482BR
<b>131-659F400; 131-704F400</b>			
Belt; W/38" Deck .....	7540329A		6630BR
<b>131-734G400</b>			
Belt; W/42" Deck .....	7540373A		6973
Transaxle .....	7540372		6881
<b>131-754F400</b>			
Belt; W/38" Deck .....	7540329A		6630BR
<b>131-824H400</b>			
Belt; W/46" Deck .....	7540349		6637BR
P.T.O. ....	7540350		6464BR
Transaxle .....	7540365		6798BR
<b>135-102TN7135</b>			
P.T.O. ....	7540443		6890
<b>136A694F</b>			
Deck; W/Cast Aluminum Spindle .....	7540329A		6630BR
Deck; W/Steel Spindle .....	7540433		6630BR
<b>136X694G</b>			
Deck .....	7540371A		6402BR
<b>140-107HG6140 Hydro</b>			
Drive .....	7540441		6417BR
P.T.O. ....	7540371A		6402BR
<b>141-844H400</b>			
Belt; W/46" Deck .....	7540349		6637BR
<b>3700-0</b>			
Blade .....	165143		6856
Trans. ....	165160		6840
<b>3700-1</b>			
Blade .....	165143		6856
Trans. ....	165181		6839
<b>3700-2</b>			
Blade .....	165143		6856
Trans. ....	165160		6840
<b>3700-3</b>			
Blade .....	165143		6856
Trans. ....	165181		6839
<b>3710-0</b>			
Blade .....	165143		6856
Trans. ....	165160		6840
<b>3720-0</b>			
Blade .....	165159		6858
Trans. ....	165160		6840
<b>3720-1; 3720-2; 3720-3</b>			
Blade .....	165183		6857
Trans. ....	165181		6839
<b>3730-0</b>			
Blade .....	165159		6858
Trans. ....	165160		6840
<b>3730-1; 3730-2; 3730-3</b>			
Blade .....	165183		6857
Trans. ....	165181		6839
<b>3760-0; 3760-1; 3770-0; 3770-1</b>			
Blade .....	165179		6978
Trans. ....	165168		6837

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD-MAN - Continued</b>			
<b>3810-1</b>			
Deck .....	7540206		6850
Drive .....	7540204		6867
Trans. ....	7540204		6867
<b>3810-1-6</b>			
Trans. ....	7540204		6867
<b>3950-1</b>			
Blade .....	165161		6961
Trans. ....	165165		6867
<b>3960-1</b>			
Deck .....	7540206		6850
Drive .....	7540204		6867
Trans. ....	7540204		6867
<b>3960-1-6</b>			
Trans. ....	7540204		6867
<b>4050-1; 4060-1; 4080-1</b>			
Deck .....	7540208		6855
Drive .....	7540207		6842
<b>4500-0; 4500-0-6</b>			
Alt./Gen. ....	7540169	7355	
P.T.O. ....	7540165		6834
<b>13251</b>			
Deck .....	7540196		6830
Trans. ....	7540188		6951
<b>13402</b>			
Blade .....	7540188		6951
Drive .....	7540187	3240	
Trans. ....	7540136		6931
<b>13413</b>			
Blade .....	7540251	3240	6809BR
Drive .....	7540187		
Trans. ....	7540136		6931
<b>13445</b>			
Blade .....	7540178	3820	6982
Trans. ....	7540200		6848
<b>13501</b>			
Belt; W/30" Belt O.C. ....	7540249		6930
Belt; W/52" Belt O.C. ....	7540264		6639BR
<b>13504</b>			
Belt; W/35" Belt O.C. ....	7540241		6494BR
Belt; W/38" Belt O.C. ....	7540240		6511BR
<b>13511</b>			
Belt; W/30" Belt O.C. ....	7540249		6930
Belt; W/52" Belt O.C. ....	7540264		6639BR
<b>13513; 13514</b>			
Deck .....	7540264		6639BR
Transaxle; W/35" Belt O.C. ....	7540241		6494BR
Transaxle; W/38" Belt O.C. ....	7540240		6511BR
<b>13517</b>			
Deck; W/50" Belt O.C. ....	7540214	2530	6850
Deck; W/53" Belt O.C. ....	7540250		6853
Transaxle; W/35" Belt O.C. ....	7540241		6494BR
Transaxle; W/38" Belt O.C. ....	7540240		6511BR
<b>13518</b>			
Belt; W/32" Deck; W/8 H.P. Eng. ....	7540347		6847BR
Blade; W/8 H.P. Eng. ....	7540290		6847
Transaxle; W/35" Belt O.C.; W/8 H.P. Eng. ....	7540241		6494BR
Transaxle; W/38" Belt O.C.; W/8 H.P. Eng. ....	7540240		6511BR
<b>13525</b>			
Blade .....	7540195		6854
Deck .....	7540195		6854
Trans. ....	7540198		6451BR
<b>13525-9; 13526</b>			
Deck .....	7540195		6854
Trans. ....	7540198		6451BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD-MAN - Continued</b>			
13565 Blade .....	7540271		6557BR
13618; 13619; 13620 Deck .....	7540195		6969
13625 Deck .....	7540195		6854
13631 Deck .....	7540195		6969
13637; 13655 Blade .....	7540329		6630BR
13665 Blade; W/12.5 H.P. Eng. ....	7540329		6630BR
13698 Belt; W/69" Belt O.C. ....	7540145		6488BR
Belt; W/85" Belt O.C. ....	7540266		6775BR
13699 Blade .....	7540271		6557BR
Trans. ....	7540266		6775BR
13705 Deck .....	7540293		6501BR
Drive .....	7540229		6852
13720 Trans. ....	7540248		6431BR
13720-0 Transaxle .....	7540248		6431BR
13735 Blade .....	7540350		6464BR
Transaxle; W/79" Belt O.C. ....	7540349		6637BR
Transaxle; W/89" Belt O.C. ....	7540248		6431BR
13745 Deck .....	7540293		6501BR
Drive .....	7540230		6755BR
Eng. ....	7540245	2590	6859
Trans. ....	7540255		6837
13760 Blade .....	7540250	2530	6853
Eng. To Input Drive .....	7540251		6809BR
Eng. To J.S. ....	7540245		6859
J.S. To Hydro. ....	7540255		6837
13770-0; 13770-8; 13770-9; 13775-8 Deck .....	7540208		6855
Drive .....	7540207		6842
13780-0 Drive .....	7540245		6859
Transaxle .....	7540154		6837
13785 Blade; W/59" Belt O.C.; W/16 H.P. Eng. ....	7540245		6859
Blade; W/64" Belt O.C.; W/16 H.P. Eng. ....	7540350		6464BR
Deck .....	7540246		6354
Eng. To Input Drive .....	7540247		6855
Eng. To J.S. ....	7540245		6859
J.S. To Hydro. ....	7540255		6837
Transaxle; W/37" Belt O.C.; W/16 H.P. Eng. ....	7540255		6837
Transaxle; W/79" Belt O.C.; W/16 H.P. Eng. ....	7540349		6637BR
13795; 13795-9 Blade .....	7540198		6451BR
Trans. ....	7540207		6842
13875-0; 13875-8; 13875-9 Deck .....	1651066		6864
Eng. To Deck .....	7540206		6850
Transaxle .....	7540204		6867
13885 Blade .....	1651066		6864
Eng. To Blade .....	7540206		6850

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD-MAN - Continued</b>			
13885 - Continued Eng. To Trans. ....	7540204		6867
14815 Blade; W/59" Belt O.C.; W/18 H.P. Eng. ....	7540245		6859
Blade; W/64" Belt O.C.; W/18 H.P. Eng. ....	7540350		6464BR
Transaxle; W/40" Belt O.C.; W/18 H.P. Eng. ....	7540244		6840
Transaxle; W/79" Belt O.C.; W/18 H.P. Eng. ....	7540349		6637BR
14823 Eng. ....	7540245		6859
Trans. ....	7540255		6837
14825 Deck .....	7540246		6354
Eng. To Input Drive .....	7540261	2560	6856
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540244		6840
14827 Deck .....	7540275		6838
Eng. To Input Drive .....	7540261	2560	6856
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540244		6840
14843 Eng. ....	7540245		6859
Hydro. ....	7540177		6832
14916 Eng. To J.S. ....	7540218		6959
J.S. To Trans. ....	7540211		6946
14918 Eng. To Variable Speed .....	7540227		6963
Variable Speed To Trans. ....	7540212		6945
14995 Eng. To P.T.O. ....	7540234		6841
138875A-8 Deck .....	1651066		6864
Eng. To Deck .....	7540206		6850
Transaxle .....	7540204		6867
<b>Farm Tractor Hydro Hi-Lo Trans</b>			
Blade; W/Woods Deck; W/22 H.P. Eng. .	1469		B133
P.T.O.; W/22 H.P. Eng. ....	7540234		6841
LT12-38 Belt; W/38", 42" Deck .....	7540229		6852
LT14-42 Belt; W/38", 42" Deck .....	7540229		6852
Belt; W/46" Deck .....	7540350		6464BR
LT18-46 Belt; W/36" Deck .....	7540167		6964
<b>YAZOO</b>			
FS60 Trans. ....			BX71
PSG-48 Blade - Center .....	205046		6848
Blade - Wing .....	205053		6855
Drive .....	205074		6976
PSG-60 Drive .....	205074		6976
PSG-60 RAD Blade - Center .....	205055		6958
Blade - Wing .....	205061		6964
PSG-76 Drive .....	205074		6976
P.T.O. Trans. ....	205073		6976
Trans. ....	205066		BX66
Red Rider Deck Drive .....	205505		6629BR

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YAZOO - Continued</b>			
<b>Red Rider - Continued</b>			
Trans .....			6830
<b>YR-6-32</b>			
Blade .....	205032	2320	
Drive .....	205360		3V600
Eng. To Deck .....	205353		3V530
Trans. ....	205036		6838
<b>YR-30</b>			
Blade .....	205353		3V530
<b>YR-32</b>			
Deck; W/69" Belt O.C. ....	205469		6869
Deck; W/90" Belt O.C. ....	205390		3V900
Gen. ....	205331		3V315
Long Wing .....	205035	2346	
Short Wing .....	205026	2260	6826
Trans. ....	205065		BX65
<b>YR-36</b>			
Blade - Center .....	205375		3V750
Blade - Left Wing .....	205024	2240	6824
Blade - Right Wing .....	205034	2340	6834
Gen. ....	205331		3V315
Trans.; Early .....	205066		BX66
Trans.; Late .....	205065		BX65
<b>YR-42</b>			
Blade - Wing .....	205141	3410	6941
Trans. ....	205070		6973
<b>YR-48</b>			
Blade - Center .....	205380		3V800
Blade - Wing .....	205144	2440	6844
Trans.; W/73" Belt O.C. ....	205070		6973
Trans.; W/74" Belt O.C. ....	205071		BX71
<b>YR-60</b>			
Blade - Center; W/Fixed Rear Wheels ...	205390		3V900
Blade - Center; W/O Fixed Rear			
Wheels .....	205395		3V950
Blade - Wing .....	205356		3V560
Trans. ....	205071		BX71
<b>YR-60 Rad.</b>			
Blade; W/55" Wing .....	205055		6958
Blade; W/61" Wing .....	205061		6964
Traction .....	205137		6940
Trans. ....	205071		BX71
<b>YR-76</b>			
Blade - Center; W/Fixed Rear Wheels ...	205390		3V900
Blade - Center; W/O Fixed Rear			
Wheels .....	205310		3V1000
Blade - Wing .....	205367		3V670
Deck .....	205310		3V1000
Trans. ....	205071		BX71
Wing Mower .....	205367		3V670
<b>YR-76 Rad.</b>			
Blade; W/55" Wing .....	205055		6958
Blade; W/61" Wing .....	205061		6964
Traction .....	205137		6940
Trans. ....	205071		BX71
<b>YZTK20</b>			
Blade; W/48" Blade .....			A100
P.T.O.; W/48" Deck .....			6985
<b>YZTK22</b>			
P.T.O. ....			6984

<b>YAZOO/KEES</b>			
<b>ZEKH4220</b>			
Hydro. Drive .....	539110411		6755BR
<b>ZEKH42200</b>			
Deck Drive .....	539112334		6566BR
Hydro. Drive .....	539104334		6756BR
<b>ZEKH48240</b>			
Deck Drive .....	539110832		6759BR
Hydro. Drive .....	539104334		6756BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YAZOO/KEES - Continued</b>			
<b>ZEKH52240</b>			
Deck Drive .....	539112335		6746BR
Hydro. Drive .....	539104334		6756BR
<b>ZELKH52250</b>			
Deck Drive .....	539114557		6597BR
Hydro. Drive .....	539111445		6553BR
<b>ZELKH61251</b>			
Deck Drive .....	539132002		6747BR
Hydro. Drive .....	539111445		6553BR
<b>ZHDD61270; ZHDD61340</b>			
Deck .....	106340		6692BR
<b>ZHDD72340</b>			
Deck .....	104335		6760BR
<b>ZKH52223; ZKH52253</b>			
Deck .....	102903		6589BR
Mule Drive .....	102548		6615BR
<b>ZKH61253</b>			
Deck .....	102549		6783BR
Mule Drive .....	102548		6615BR
<b>ZKHP52233; ZKHP52253</b>			
Deck .....	102903		6589BR
Mule Drive .....	102548		6615BR
<b>ZKHP61253</b>			
Deck .....	102549		6783BR
Mule Drive .....	102548		6615BR
<b>ZKW42170; ZKW42171; ZKW42172; ZKW42182</b>			
Deck .....	103240		6787BR
Pump .....	103241		6735BR
<b>ZKW48170</b>			
Pump .....	103241		6735BR
<b>ZKW52233</b>			
Deck .....	102903		6589BR
Mule Drive .....	102548		6615BR
<b>ZKW61233</b>			
Deck .....	102549		6783BR
Mule Drive .....	102548		6615BR
<b>ZKWQL42171; ZKWQL42182</b>			
Deck .....	103240		6787BR
Pump .....	103241		6735BR
<b>ZKWQL48170</b>			
Deck .....	103687		6732BR
Pump .....	103241		6735BR
<b>ZKWQL48171</b>			
Pump .....	103241		6735BR
<b>ZKWQL48182</b>			
Pump .....	103241		6735BR
<b>ZKWQL48190</b>			
Deck .....	103687		6732BR
Pump .....	103241		6735BR
<b>ZKWQL48191</b>			
Pump .....	103241		6735BR
<b>ZKWQL48212</b>			
Pump .....	103241		6735BR
<b>ZMKW5222</b>			
Deck Drive .....	539112335		6746BR
Hydro. Drive .....	574870901		7007BR
<b>ZMKW6124</b>			
Deck Drive .....	522811401		6853BR
Hydro. Drive .....	574870901		7007BR
<b>ZPKW5426</b>			
Deck Drive .....	574285901		6878BR
Hydro. Drive .....	573978301		6675BR
<b>ZPKW6029</b>			
Deck Drive .....	522829601		6879BR
Hydro. Drive .....	573978301		6675BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YAZOO/KEES - Continued</b>			
<b>ZVHO52241</b>			
Deck .....	104335		6760BR
Pump .....	104334		6756BR
<b>ZVHO61241; ZVKE61260; ZVKE61261</b>			
Deck .....	104336		6761BR
Pump .....	104334		6756BR
<b>ZVKE72260; ZVKE72261</b>			
Deck .....	105477		6934BR
Pump .....	104334		6756BR
<b>ZVKH52230; ZVKH52231</b>			
Deck .....	104335		6760BR
Pump .....	104334		6756BR
<b>ZVKH61250; ZVKH61251; ZVKH61270; ZVKH61271</b>			
Deck .....	104336		6761BR
Pump .....	104334		6756BR
<b>ZVKH61273; ZVKH61303</b>			
Deck Drive .....	539104336		6761BR
Hydro. Drive .....	539104334		6756BR
<b>ZVKH72270; ZVKH72271</b>			
Deck .....	105477		6934BR
Pump .....	104334		6756BR
<b>ZVKH72303</b>			
Deck Drive .....	539105477		6934BR
Hydro. Drive .....	539104334		6756BR
<b>ZVKHL61230; ZVKHL61231</b>			
Deck .....	104336		6761BR
Pump .....	104334		6756BR
<b>ZVKW52230; ZVKW52231; ZVKW52250; ZVKW52251</b>			
Deck .....	104335		6760BR
Pump .....	104334		6756BR
<b>ZVKW52253</b>			
Deck Drive .....	539104335		6760BR
Hydro. Drive .....	539104334		6756BR
<b>ZVKW61230; ZVKW61231; ZVKW61250; ZVKW61251</b>			
Deck .....	104336		6761BR
Pump .....	104334		6756BR
<b>ZIPPER</b>			
<b>Zipper-TS</b>			
Blade .....			B120
Blower .....			6849
P.T.O. ....	B50		6953

Lawn & Garden Equipment



Manufacturers' Part Number Shown for Reference Only

Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE</b>			
12A-379B Drive	7540271		6557BR
120-250 Drive	7540163		6828
120-277; 120-279; 120-290 Belt	7540114	2240	6824
120-350 Drive	7540935	2310	6831
121-280; 121-290; 121-292; 122-290; 122-292 Belt	7540114	2240	6824
122-690; 122-692 Traction	7540239	2290	6829
123-290; 123-295 Belt	7540114	2240	6824
123-690 Traction	7540239	2290	6829
124-280; 124-290; 124-290A; 124-295A Belt	7540114	2240	6824
124-350 Drive	7540935	2310	6831
124-364; 124-376 Traction	7540252		6833
125-230 Belt	7540242	2320	6832
125-290; 125-295 Belt	7540114	2240	6824
126-214 Drive	7540104		6832
126-230 Belt	7540242	2320	6832
126-270; 126-290; 126-290A Belt	7540114	2240	6824
126-350 Drive	7540935	2310	6831
126-367 Drive	7540292		6826
126-560 Blade	7540326	6862	
126-560 Traction	7540327	6928	
127-212; 127-214; 127-216 Drive	7540104		6832
127-322; 127-335 Drive	7540163		6828
127-350 Drive	7540935	2310	6831
127-355; 128-250; 128-255 Drive	7540163		6828
128-275 Belt	7540114	2240	6824
128-335 Drive	7540163		6828
128-350 Drive	7540935	2310	6831
129-250; 129-335 Drive	7540163		6828
129-350 Drive	7540935	2310	6831
70396A Blade	7540109		6843

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE - Continued</b>			
70398 Belt	7540114	2240	6824
70399 Blade	7540109		6843
70399 Drive	7540935	2310	6831
70399 Traction	7540121		6831
70400 Drive	7540126		6820
71261 Belt	7540114	2240	6824
71281CL Blade	7540125		6428BR
71633 Blade	7540144	3550	6955
71633 Traction	7540143		6728
72056 Traction	7540239	2290	6829
72425 Drive	7540935	2310	6831
74065 Blade	7540264		6639BR
74065 Primary Variator	7540241		6494BR
74065 Secondary Variator	7540240		6511BR
500647 Drive	5006471	1380	6738
<b>ACER EASE</b>			
003700 Belt			6958
C60K Belt			B124
H40B Belt			6865
<b>AGWAY</b>			
52-1257; 52-1301 Traction	7540114	2240	6824
52-1306 Hi Wheel Belt			6843
52-1307 Hi Wheel; 52-1308 Hi Wheel Blade	7540109		6843
52-1307 Hi Wheel; 52-1308 Hi Wheel Trans.	7540104		6832
52-1311; 52-1312; 82-0014; 82-0025; 82-0034 Traction	7540114	2240	6824
82-0309 Belt	7540126		6820
82-0609 Belt	7540252		6833
82-0631 Traction	7540114	2240	6824
82-0632 Belt	7540252		6833
92-0304; 116-234; 120-274; 121-290; 122-290; 123-290 Traction	7540114	2240	6824
<b>AIRCAP</b>			
560B Blade	7540326		6862
2521; 9221; 9821 Traction	10661		6840





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AIRCAP - Continued</b>			
AP461P Belt	538	1310	6731
AP462 Belt	644	1350	6735
C-12SP2 3/4 Drive	SP2		6827
CR461P Belt	538	1310	6731
CR462 Belt	644	1350	6735
PM461P Belt	538	1310	6731
PM462 Belt	644	1350	6735
<b>AIR-ELECTRIC</b>			
B20 Blade	B1		6839
C-12SP2 3/4 Traction	SP2		6827
<b>ALDENS</b>			
500-002 Hi Wheel Belt	7540109		6843
550-002 Hi Wheel Blade	7540109		6843
550-002 Hi Wheel Trans.	7540104		6832
<b>ALLIED HARDWARE</b>			
110-500; 111-500; 112-500; 113-500; 114-500; 118-500 Belt	7540116	2420	6842
120-560; 120-570 Blade	7540144	3550	6955
120-560; 120-570 Traction	7540143		6728
121-550 Blade	7540109		6843
121-550 Drive	7540121		6831
122-550 Blade	7540109		6843
122-550 Traction	7540242	2320	6832
122-690 Belt	7540239	2290	6829
123-550 Blade	7540109		6843
123-550 Drive	7540121		6831
123-690 Belt	7540239	2290	6829
124-260; 124-290 Belt	7540114	2240	6824
124-550 Blade	7540109		6843
124-550 Drive	7540121		6831
125-290 Belt	7540114	2240	6824
128-550 Blade	7540109		6843
128-550 Drive	7540121		6831
<b>AMERICAN HARDWARE</b>			
150-518; 151-518; 152-518; 153-518; 154-518; 3736; 21863 Belt	7540126		6820
33537 Blade	7540274		6844
33537 Drive	7540146		6833

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN HARDWARE - Continued</b>			
36736 Belt	7540126		6820
39509 Belt	7540935	2310	6831
41632; 41633 Trans.	7540252	2330	6833
Carlton 123-690 Belt	7540239	2290	6829
Georgetown 122-292 Belt	7540114	2240	6824
Glenville 113-500 Belt	7540116	2420	6842
Highland 122-570; Highland 123-570; Highland 124-570 Blade	7540144	3550	6955
Highland 122-570; Highland 123-570; Highland 124-570 Trans.	7540143		6728
Middlebury 124-350 Belt	7540935	2310	6831
Servistar 120-337 Trans.	7540252	2330	6833
Servistar 120-350 Belt	7540935	2310	6831
Westbrook 122-294; Westbrook 123-290; Westbrook 124-290; Westbrook 125-290 Belt	7540114	2240	6824
<b>AMERICAN HARDWARE SERVISTAR</b>			
128-250 Drive	7540163		6828
39509 Drive	7540935	2310	6831
<b>AMERICAN YARD PROD.</b>			
3C402A; 3C402B; 3H402A; 3H402B; 3H402C; 3M402A; 3M402B; 3M402C; 3P402A; 3P409B Drive	137078		6460BR
4C472A; 4C472B; 4E482A; 4E482B; 4H472A; 4H472B; 4H472C; 4H472D; 4H472F; 4H473A Drive	137078		6460BR
4H473B; 4H473C; 4H482A; 4M472A; 4M472C; 4P472A; 4V582A; 4V582B; 917.372800; 917.372850 Drive	137078		6460BR
3232A59; 3256A59; 4258A59; 5155A59; 5255A59; ABP841A; AN4H479A; AN4H479B; AN7T909A; AN7T909B Drive	137078		6460BR
AP50E; AYP1155A69; AYP1232A69; AYP2256A69; AYP3232A49; AYP3232A59; AYP3232A69; AYP3256A49; AYP3256A59; AYP3256A69 Drive	137078		6460BR
AYP3256B49; AYP4258A49; AYP4258A59; AYP5155A49; AYP5155A59; AYP5155A69; AYP5255A59; BM4H479B; BM4M479A; BM4Z411A Drive	137078		6460BR
BP256B; BP256C; BP575A; BP575B; CD4H472A; CD4H472B; CD4H472C; CP3R402A; CP4S486A; CP4S486B Drive	137078		6460BR
CP90A; CPP50B; CPP55A; CT50A; CT50B; CT75A; CT75B; CT75C; CT905A; CT905B Drive	137078		6460BR

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN YARD PROD. - Continued</b>			
CT905C; CT905D; ENM5604A; ESRB2255A; EZ4H479A; EZ4H479B; GM3E402A; GM3R402A; GM4H472A; GM4H472B			6460BR
Drive ..... 137078			
HD3T402A; HD3T402B; HD4I486A; HD4T586A; HD7I402A; HD7I402B; HD7T402A; HD7T402B; HD8I186B; HD8I486A			6460BR
Drive ..... 137078			
HD8I486B; HD8I486C; HD8I486D; HD8I486E; HM3C409A; HM3M401A; HW906B; HW906C; HW906D; HWRB2255A			6460BR
Drive ..... 137078			
HWRB2255B; HWS DSP225B; HWSP2525A; HWSP2525B; HWSP2525C; KRSP2255; MJC7S402A; MJC85B; MJC85C; MJC86A			6460BR
Drive ..... 137078			
MJC86B; MJC86C; MJC86D; MJC455A; MJC455B; MJC9656RA; RBSP225A; RBSP225B; RBSP225C; RBSP225D			6460BR
Drive ..... 137078			
RBSP225E; RBSP225F; RBSP225QA; RE3H402A; RE4H472A; SDSP224A; SDSP224QA; SDSP224QB; SDSP224QC; SDSP2245A			6460BR
Drive ..... 137078			
TAP50B; TAP50C; TAP50D; TAP50E; WE3E402A; WE3M402A; WE4H476A; WE4H476B; WE7S402A; WE7S402B			6460BR
Drive ..... 137078			
WE464SA; WE640SB; WE642SA; WE645SB; WE646SA; WE646SB; WE647SA; WE651SHA; WE651SHB; WE652SHA			6460BR
Drive ..... 137078			
WE652SHB; WE653SHA; WE944RA; WE944RB; WE960RA; WE961RA; WE962RA; WE963RA; WE964RA; WE965RB			6460BR
Drive ..... 137078			
WE966RA; WE966RB; WE967RHB; WE969RA; WE975REB; WE976REA; WE976REB; WE977REA; WE983RA; WE986RA			6460BR
Drive ..... 137078			
WE986RB; WE986RC; WE6445SA; WE6445SB; WE6445SC; WE6452SA; WE6452SB; WE6452SC; WE6452SD; WE6502SHA			6460BR
Drive ..... 137078			
WE9652RA; WE9652RB; WE9656RA; WE9656RB; WE9656RC; WE9656RD; WE9752REA; WE9756RA; WE9756REA; WE9756REB			6460BR
Drive ..... 137078			
WE9756REC; WET975REA; WET975REB; X252B; Y4K482A; Y4W482A; Y4X482A; Y7K402A; Y7L909A; Y7W402A			6460BR
Drive ..... 137078			
Y7X402A; Y8K472A; YSC4K482A; YSC4K482B; YSC4K482C; YSC4K482D; YSC7K402A; YSC7K402B; YSC7K402C; YSC7K402D			6460BR
Drive ..... 137078			
YSC8K472A; YSC8K472C; YSC8K472D			6460BR
Drive ..... 137078			
<b>ARIENS</b>			
907254			6689BR
Blade ..... 72171			

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
911005; 911006; 911007; 911008; 911009; 911010; 911011; 911012; 911013; 911014			6733
Traction ..... 72138			
911015; 911016; 911017; 911018; 911019; 911020; 911023; 911024; 911026; 911027			6733
Traction ..... 72138			
911028; 911029; 911030; 911031; 911032			6733
Traction ..... 72138			
911033; 911034; 911035; 911036; 911037; 911038; 911040; 911041; 911042; 911043			6689BR
Blade ..... 72171			
911044; 911045; 911046; 911047; 911048; 911049; 911050; 911051; 911052; 911053			6689BR
Blade ..... 72171			
911054; 911055; 911056; 911057; 911058; 911059; 911060; 911061; 911062; 911063			6689BR
Blade ..... 72171			
911064; 911065; 911068; 911069; 911070; 911071; 911072; 911073			6689BR
Blade ..... 72171			
911271			6736
Drive ..... 07200114			
911311; 911312; 911313; 911314; 911315; 911316; 911317; 911318; 911319			6689BR
Blade ..... 72171			
911410			6809BR
Blade Drive ..... 07234300			
Eng. To Deck ..... 07243300			6674BR
911468; 911469; 911470; 911471; 911472; 911473			6689BR
Blade ..... 72171			
<b>Classic LM21 S; Classic LM21 SW</b>			
Drive ..... 07217100			6689BR
<b>LM Models</b>			
Drive ..... 72138			6733
<b>Professional Walk 36GR</b>			
Deck ..... 00201010			6815BR
Traction ..... 07400037			7124BR
<b>Professional Walk 48GR</b>			
Blade Drive ..... D38019			6993BR
Eng. To Deck ..... 07200533			6812BR
Traction ..... 07400037			7124BR
<b>Razor ES; Razor SP; Razor SP BBC</b>			
Drive ..... 07200633			6733
<b>Wide Area Walk 34</b>			
Blade Drive ..... 07234300			6809BR
Eng. To Deck ..... 07243300			6674BR
<b>ATLAS</b>			
718R; 721R			6829
Belt ..... 1074			
<b>BW100</b>			
Belt; W/48" Belt O.C. ....			6848
Belt; W/50" Belt O.C. ....			3V500
<b>EHP22B; H20SP; H22SP</b>			
Drive ..... 10717			6730
<b>HD99; HD100; HD100A; HD200; HD200A; HD300; HD300A</b>			
Belt ..... 10712			6831
<b>HP20; HP22; HP22A; HP22B</b>			
Drive ..... 10717			6730
<b>L22G5; L22GP8</b>			
Blade ..... L115		2410	6841
Drive; W/18" Belt O.C. .... 218		2180	6818
Drive; W/25" Belt O.C. .... 219		2250	6825



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ATLAS - Continued</b>			
<b>M20G3; M20GP5</b>			
Blade .....	M115	2380	6838
Drive; W/18" Belt O.C. ....	218	2180	6818
Drive; W/25" Belt O.C. ....	219	2250	6825
<b>M110; M110A</b>			
Blade .....	10718	2430	
<b>M310; M310A</b>			
Blade .....	10718	2430	
Drive .....	10719	2280	
<b>M2100</b>			
Blade .....	10718	2430	
<b>M2170; M2171</b>			
Blade .....	10718	2430	
Drive .....	10719	2280	
<b>NHP22B</b>			
Drive .....	10717		6730
<b>RL18; RL18A; RL21; RL21A</b>			
Belt .....	1074		6829
<b>SB19G3</b>			
Blade .....	219	2250	6825
<b>SP22; SP22A; SP22AA; SP22AW; SP22B; SP223; SP300A</b>			
Belt .....	1071	1290	6729
<b>AUTOMOTIVE ASSOCIATES</b>			
<b>115-500</b>			
Belt .....	7540109		6843
<b>118-500</b>			
Belt .....	7540116	2420	6842
<b>120-220</b>			
Belt .....	7540242	2320	6832
<b>120-270; 120-272</b>			
Belt .....	7540114	2240	6824
<b>120-550</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>121-220</b>			
Belt .....	7540242	2320	6832
<b>121-290; 121-292</b>			
Belt .....	7540114	2240	6824
<b>121-550</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>122-280; 122-290</b>			
Belt .....	7540114	2240	6824
<b>122-550</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>122-690</b>			
Belt .....	7540239	2290	6829
<b>123-220</b>			
Belt .....	7540242	2320	6832
<b>123-270; 123-280; 123-290</b>			
Belt .....	7540114	2240	6824
<b>123-550</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>123-693</b>			
Belt .....	7540239	2290	6829
<b>124-280; 124-290</b>			
Belt .....	7540114	2240	6824
<b>124-350</b>			
Belt .....	7540163		6828

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AUTOMOTIVE ASSOCIATES - Continued</b>			
<b>124-550</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>124-690</b>			
Belt .....	7540239	2290	6829
<b>125-280; 125-290</b>			
Belt .....	7540114	2240	6824
<b>125-350</b>			
Belt .....	7540163		6828
<b>125-550</b>			
Blade .....	7540109		6843
Drive .....	7540177		6832
Traction .....	7540121		6831
<b>126-241</b>			
Belt .....	7540242	2320	6832
<b>126-270; 126-280; 126-290</b>			
Belt .....	7540114	2240	6824
<b>126-350</b>			
Belt .....	7540163		6828
<b>126-500</b>			
Belt .....	7540109		6843
<b>126-550</b>			
Blade .....	7540109		6843
<b>127-350; 127-355</b>			
Belt .....	7540163		6828
<b>127-550</b>			
Blade .....	7540109		6843
Drive .....	7540177		6832
<b>128-220; 128-241</b>			
Belt .....	7540242	2320	6832
<b>128-272</b>			
Belt .....	7540114	2240	6824
<b>128-451</b>			
Belt .....	7540935	2310	6831
<b>128-550; 128-552</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>129-220; 129-240</b>			
Belt .....	7540242	2320	6832
<b>129-270</b>			
Belt .....	7540114	2240	6824
<b>154-510; 154-520; 156-510; 156-520</b>			
Belt .....	7540100	2180	6818
<b>BAD BOY MOWERS</b>			
<b>3600 Walk-Behind</b>			
Deck Drive .....	041-5200-00		7041BR
Pump .....	041-6500-00		6530BR
<b>4800 Walk-Behind</b>			
Deck Drive .....	041-1560-00		6997BR
Pump .....	041-6500-00		6530BR
<b>BIGDOG MOWERS</b>			
<b>HIKE</b>			
Deck Drive; W/36" Deck .....	601786		6709BR
Deck Drive; W/48" Deck .....	601969		6918BR
Deck Drive; W/54" Deck .....	601788		6646BR
Hydro. Pump; W/36" Deck .....	601838		6734BR
Hydro. Pump; W/48" & 54" Deck .....	793836		6847BR
<b>T-36</b>			
Deck Drive .....	601786		6709BR
Hydro. Pump .....	601838		6734BR
<b>T-48</b>			
Deck Drive .....	601969		6918BR
Pump Drive .....	793836		6847BR

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BIGDOG MOWERS - Continued</b>			
T-54			
Deck Drive .....	601788		6646BR
Pump Drive .....	793836		6847BR

<b>BILLY GOAT INDUSTRIES</b>			
HP3400			
Blade Drive .....	521112		6960
Transaxle .....	521122		6833
HW650SP			
Blade Drive .....	510139	3560	
Drive .....	510138	1320	
HW651HSP; HW651SP			
Blade Drive .....	510139	3560	
Traction .....	510138	1320	

<b>BLACK &amp; DECKER</b>			
U-173; U-273			
Belt .....	62398		6183

<b>BLACK, SIVALLS AND BRYSON</b>			
18R31C-LP; 18R31C-V; 18R31C-W; 18R31LP; 18R31V; 18R31W; 18R41-MK; 18R41-MM; 21R31C-LP; 21R31C-W			
Belt .....	27411	2240	6824
21R31-LP; 21R31V; 21R31W; A18R41; A18R631; A21R41			
Belt .....	27411	2240	6824
A21SP-631; ASP-141			
Belt .....	6A73002	2360	6836
HW-451-MK			
Belt .....	6A73003	2340	6834
Lasp-141			
Belt .....	6A73001	2350	6835
LSP-1X51-MK			
Belt .....	6A73002	2360	6836
LSP-131-LP; LSP-131-W			
Belt .....	6A73003	2340	6834
LSP-141-LP; LSP-141-W; LSP-1051-MM			
Belt .....	6A73001	2350	6835
LSP-1052-MM			
Belt .....	6A73002	2360	6836
LSP-1052-WO			
Belt .....	6A73001	2350	6835
SP-1X51-MK			
Belt .....	6A73004	2370	6837
SP-132-LP; SP-132-V; SP-132-W; SP-141-M; SP-142-LP; SP-142-W			
Belt .....	6A73002	2360	6836

<b>BLACK &amp; DECKER</b>			
U-173; U-273			
Belt .....	62398		6183

<b>BLACK, SIVALLS AND BRYSON</b>			
18R31C-LP; 18R31C-V; 18R31C-W; 18R31LP; 18R31V; 18R31W; 18R41-MK; 18R41-MM; 21R31C-LP; 21R31C-W			
Belt .....	27411	2240	6824
21R31-LP; 21R31V; 21R31W; A18R41; A18R631; A21R41			
Belt .....	27411	2240	6824
A21SP-631; ASP-141			
Belt .....	6A73002	2360	6836
HW-451-MK			
Belt .....	6A73003	2340	6834
Lasp-141			
Belt .....	6A73001	2350	6835
LSP-1X51-MK			
Belt .....	6A73002	2360	6836
LSP-131-LP; LSP-131-W			
Belt .....	6A73003	2340	6834
LSP-141-LP; LSP-141-W; LSP-1051-MM			
Belt .....	6A73001	2350	6835
LSP-1052-MM			
Belt .....	6A73002	2360	6836
LSP-1052-WO			
Belt .....	6A73001	2350	6835
SP-1X51-MK			
Belt .....	6A73004	2370	6837
SP-132-LP; SP-132-V; SP-132-W; SP-141-M; SP-142-LP; SP-142-W			
Belt .....	6A73002	2360	6836

<b>BLUE GRASS</b>			
124-364			
Traction .....	7540252		6833
B280-4			
Belt .....	7540114	2240	6824
BG18BSP9; BG18SP; BG18SP8; BG18WSP; BG21DSP9; BG21SP8; BG21WSP			
Belt .....	GRP82		6723
BG61GS; BG63GP; BG63GPA			
Belt .....	17137	2170	6817
BG65SP; BG66SP; BG69SPE; BG70SP			
Belt .....	17138	2230	6823
BG290SP-D; BG294-4			
Belt .....	7540114	2240	6824
BG618SPD; BG621SP; BG621SPD			
Belt .....	GRP82		6723

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BLUE GRASS - Continued</b>			
BG5318 DR; BG5318A; BG5321 DR; BG5321A; BG5918; BG5921; BG6118; BG6118H; BG6121; BG6121H			
Belt .....	17137	2170	6817
BR18GS; BR61GS; PG66AP			
Belt .....	17137	2170	6817
W3-1720; W3-1820-73			
Belt .....	1230	2400	6840
W3-1820SP-73			
Blade .....	1242	2340	6834
W3-1822-73			
Belt .....	1237	2440	6844
W3-1822SP-73			
Blade .....	1236	2390	6839
W3-1830SP-73			
Blade .....	1231		6872
W7-BG290SP			
Belt .....	7540114	2240	6824
W7-BG335SP			
Trans. ....	7540163		6828

<b>BOBCAT</b>			
21" SP Mower			
Wheel Drive .....	78030N		6435BR
48" Hydro Mower			
Deck .....	38440		6702BR
48" SD Mower			
Eng. To Deck .....	38442		6527BR
121-4SP ZIC			
J.S. To Wheel Drive .....	78031N		6433BR
930300; 930301; 930302; 930303; 930304; 930306; 930307; 930309; 930310			
Hydro. ....	2308052		6529BR
932006			
Blade Drive .....	2721255		6812BR
Gear Box .....	2721796		7008BR
Trans. ....	2721477		6823BR
932007; 932007G; 932007J			
Deck Drive .....	2721255		6812BR
Gear Box .....	2721796		7008BR
Trans. ....	2721477		6823BR
933006			
Blade Drive .....	4128848		6814BR
Gear Box .....	2721796		7008BR
Trans. ....	38212		6436BR
933007; 933007G; 933007J			
Deck Drive .....	4128848		6814BR
Gear Box .....	2721796		7008BR
Trans. ....	38212		6436BR
933301; 933302			
Blade Drive .....	2721477		6823BR
Eng. To Deck .....	2721478		6702BR
Hydro. ....	2721642		7011BR
933305; 933305G; 933305J; 933307; 933307G; 933330; 933331; 933331G			
Blade Drive .....	2721477		6823BR
Eng. To Deck .....	2721478		6702BR
Hydro. ....	2721642		7011BR
934006			
Blade Drive .....	4128718		6688BR
Gear Box .....	2721796		7008BR
Trans. ....	38212		6436BR
934007; 934007G; 934007J			
Deck Drive .....	4128718		6688BR
Gear Box .....	2721796		7008BR
Trans. ....	38212		6436BR



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOBCAT - Continued</b>				<b>BOBCAT - Continued</b>			
<b>934301</b>				<b>M36-11</b>			
Blade Drive .....	128110		6615BR	Blade .....	38111		6814BR
Hydro .....	2721642		7011BR	Spindle .....	38031		6952
<b>934302; 934306; 934306G; 934306J; 934307;</b>				Traction .....	38017		6944
<b>934307G; 934307J; 934330; 934332; 934332G</b>				Variable Speed .....	38016		6936
Blade Drive .....	128110		6615BR	<b>M36-12</b>			
Hydro .....	2721642		7011BR	Drive .....	38017		6944
<b>934332J</b>				<b>M48</b>			
Blade Drive .....	128110		6615BR	Wheel Drive .....	38212		6436BR
Hydro .....	2721642		7011BR	<b>M48-1</b>			
<b>935301</b>				Blade .....	38111		6814BR
Blade Drive .....	2188176		6574BR	Spindle .....	38031		6952
Eng. To Deck .....	2722570		6644BR	Traction .....	38017		6944
Hydro .....	2721642		7011BR	Variable Speed .....	38016		6936
<b>935302; 935308; 935308G; 935308J; 935309;</b>				<b>M48-11</b>			
<b>935309G; 935330; 935333; 935333G</b>				Blade - Left .....	38030		6993
Blade Drive .....	2188176		6574BR	Blade - Right .....	38031		6952
Eng. To Deck .....	2722570		6644BR	Traction .....	38017		6944
Hydro .....	2721642		7011BR	Variable Speed .....	38016		6936
<b>936600; 936600J</b>				<b>M48-12</b>			
Blade Drive .....	128110		6615BR	Drive .....	38017		6944
Hydro .....	2721642		7011BR	<b>M48-16</b>			
<b>936601; 936601J</b>				Spindle - Center & Left .....	38030		6993
Blade Drive .....	2188176		6574BR	Spindle - Center & Right .....	38031		6952
Hydro .....	2721642		7011BR	Traction .....	38017		6944
<b>936602; 936602J</b>				<b>M48-16A</b>			
Blade Drive .....	128003		6485BR	J.S. To Wheel Drive .....	78031N		6433BR
Hydro .....	2721642		7011BR	Variable Speed .....	38016		6936
<b>Gear Mower</b>				<b>M54-12KA</b>			
P.T.O. ....	38330		6644BR	Blade; W/82" Belt O.C. ....	38039N		6573BR
Trans.; New Style .....	128099		6528BR	Blade; W/93" Belt O.C. ....	38030N		6703BR
Wheel Drive; W/5-Speed Drive; W/36",				Variable Speed .....	38016		6936
48" Deck .....	38212		6436BR	<b>MS21-4SP</b>			
Wheel Drive; W/Variable Speed Drive;				J.S. To Wheel Drive .....	78031N		6433BR
W/36", 48" Deck .....	38249		6813BR	<b>SM3211</b>			
<b>Hydro Mower</b>				Blade Drive .....	38111		6814BR
P.T.O. ....	38330		6644BR	<b>SM4805; SM4806</b>			
Trans. ....	2308052		6529BR	Wheel Drive .....	38017N		6429BR
<b>M18-4TX; M18-35B; M21-4B</b>				<b>SM5400; SM5401</b>			
Drive .....	38017		6944	Belt .....	38030N		6703BR
<b>M21-4SP; M21-4TC</b>				<b>TR12B; TR15B</b>			
J.S. To Wheel Drive .....	78031N		6433BR	Drive To Gear Box .....	108173		6927
<b>M21-4TX; M21-5HD</b>				Float Unit Reel; W/50" Belt O.C. ....	108162		6950
Drive .....	38017		6944	High Speed Reel; W/46" Belt O.C. ....	108024		6946
<b>M21-35B; M21-ESP; M21-SP</b>				Reel Drive; W/52" Belt O.C. ....	108025		6952
J.S. To Wheel Drive .....	78031N		6433BR	<b>XD5001; XD5002</b>			
<b>M32-10</b>				Deck; Ser. No. 1185 & After .....	S81B110		B110
Blade .....	38075		6982	Main Drive; Ser. No. 1210 & After .....	S81B043		6946
Traction .....	38017		6944	<b>XM3203; XM3204</b>			
Variable Speed .....	38016		6936	Drive .....	38017		6944
<b>M32-11</b>				<b>XM3205</b>			
Blade .....	38111		6814BR	Wheel Drive .....	38017N		6429BR
Spindle .....	38031		6952	<b>XM3601; XM3602</b>			
Traction .....	38017		6944	Variable Speed .....	38016N		B33
Variable Speed .....	38016		6936	<b>XM3605; XM3606; XM3611</b>			
<b>M32-12; M32-12KA</b>				Wheel Drive .....	38017N		6429BR
Drive .....	38017		6944	<b>XM3620; XM4801; XM4802</b>			
Variable Speed .....	38016N		B33	Variable Speed .....	38016N		B33
<b>M32R</b>				<b>XM5402; XM5403</b>			
Drive .....	38017		6944	Blade .....	38030N		6703BR
<b>M36</b>				Variable Speed .....	38016N		B33
Blade; W/83" Belt O.C. ....	38275		6705BR	<b>XM5480</b>			
Blade; W/91" Belt O.C. ....	38234		6704BR	P.T.O. ....	38030N		6703BR
Wheel Drive .....	38212		6436BR	<b>XT2030</b>			
<b>M36-10</b>				Deck .....	S81B110		B110
Blade .....	38075		6982	Main Drive .....	S81B043		6946
Traction .....	38017		6944				
Variable Speed .....	38016		6936				



# WALK BEHIND MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS</b>			
433A; 433C; 433C01 Belt .....	1108454	2210	6821
438B; 438B01; 441B; 441B01 Belt .....	1108453	2200	6820
443C01; 448B Belt .....	1108454	2210	6821
448B01 Belt .....	1108453	2200	6820
451A Belt .....	1108454	2210	6821
451B01; 6451 Belt .....	1108453	2200	6820
6451-02 Belt .....	1108454	2210	6821
6544 Drive .....	1723661		6741
8324 Belt .....	1894063	1280	6728
8325-01; 8335-01; 8335-02; 8337-01; 8337-02; 8337-03 Belt .....	1894272		6735
8341-01 Belt .....	1894335		6736
8341-02; 8341-03; 8341-04 Belt .....	1894272		6735
8342-01 Belt .....	1894335		6736
8342-02; 8342-03; 8342-04 Belt .....	1894272		6735
8343-01; 8343-02; 8343-03; 8344-01 Belt .....	1894335		6736
8344-02; 8344-03 Belt .....	1894272		6735
8444; 8544; 8545; 8548; 8554; 8555; 8556; 8643; 8644; 8645 Drive .....	1723661		6741
8648; 8649; 9544; 9545; 9644; 9645 Drive .....	1723661		6741
<b>BRAVE INDUSTRIES</b>			
Warrior Belt .....			6958
Eng. To Deck .....	2640		
<b>BRISTERS THUNDER KARTS</b>			
High Wheel Champ B-22 Spindle; W/4 H.P. Eng. ....			6860
Traction; W/4 H.P. Eng. ....			6833
High Wheel Champ B-24; S/P 24; S/P 26 Spindle; W/5 H.P. Eng. ....			6862
Traction; W/5 H.P. Eng. ....			6835
S/P-22 Spindle; W/4 H.P. Eng. ....			6860
Traction; W/4 H.P. Eng. ....			6833
<b>BROUWER</b>			
Center Reel; Left Reel; Right Reel Drive .....	16C1700		6967
Vertical Mower Drive; W/71" Belt O.C. ....			BX68
Drive; W/81" Belt O.C. ....			6981
<b>BUNTON</b>			
22SFP Drive .....	G851		6832

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BUNTON - Continued</b>			
24 Blade .....	L19		6836
Eng. To Deck .....	L21		6839
Eng. To Variator .....	L148		6828
Traction .....	L20		6837
24JR Blade .....	H121		6854
Traction .....	L19		6836
25 Elite Traction .....			6944
28 Blade .....	L21		6839
Eng. To Deck .....	L643		6850
Eng. To Variator .....	L148		6828
Traction .....	L619		6944
32 Eng. To Deck .....	L511		6954
Traction .....	L619		6944
32" Walk Behind Mower Eng. To Blade .....	PL0511		6590BR
36 Blade .....	L643		6850
Traction .....	L619		6944
36" Walk Behind Mower Eng. To Blade .....	PL0511		6590BR
Wheel Drive .....	PL4275		6466BR
36HR Blade .....	L643		6850
Traction .....	L619		6944
48" Walk Behind Mower Wheel Drive .....	PL4275		6466BR
52 Blade .....	L643		6850
Traction .....	L619		6944
52" Walk Behind Mower Wheel Drive .....	PL4275		6466BR
52HR Blade .....	L643		6850
Traction .....	L619		6944
154814BV Traction .....	PL8153		6947
630301; 630304; 630306; 630307; 630310 Hydro. Drive .....	2308052		6529BR
632006 Deck Drive .....	2721255		6812BR
Gear Box .....	2721796		7008BR
Trans. ....	2721477		6823BR
633006 Deck Drive .....	4128848		6814BR
Gear Box .....	2721796		7008BR
Trans. ....	38212		6436BR
633301; 633302; 633330 Blade Drive .....	2721477		6823BR
Eng. To Deck .....	2721478		6702BR
Hydro. Drive .....	2721642		7011BR
634006 Deck Drive .....	4128718		6688BR
Gear Box .....	2721796		7008BR
Trans. ....	38212		6436BR
634301; 634302; 634330 Blade Drive .....	128110		6615BR
Hydro. Drive .....	2721642		7011BR
635301; 635302; 635330 Blade Drive .....	2188176		6574BR
Eng. To Deck .....	2722570		6644BR
Hydro. Drive .....	2721642		7011BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BUNTON - Continued</b>			
<b>B24</b>			
Blade .....	PL0019		6836
Drive .....	PL0020		6837
Eng. ....	PL0148		6828
Eng. To Deck .....	PL0021		6838
<b>B28</b>			
Blade .....	PL0021		6838
Drive .....	PL0619		6429BR
Eng. ....	PL0148		6828
Eng. To Deck .....	PL0643		6553BR
<b>B32L-8J</b>			
Traction .....	PL0619		6429BR
<b>B36</b>			
Blade .....	PL0643		6553BR
Drive .....	PL0619		6429BR
Eng. To Deck .....	PL0661		6958
<b>B36-11BIC</b>			
Blade .....	PL0643		6553BR
Trans. ....	PL0848		6940
Wheel Drive .....	PL0619		6429BR
<b>B48-125K</b>			
Traction .....	PL0619		6429BR
<b>B52</b>			
Blade .....	PL0643		6553BR
Eng. To Deck .....	PL0861		6946
Traction .....	PL0619		6429BR
<b>B52T-11H</b>			
Blade .....	PL0643		6553BR
Mower Drive .....	PL0661		6958
Trans. ....	PL0848		6940
Wheel Drive .....	PL0619		6429BR
<b>BP2L-1250N</b>			
Traction .....	PL0619		6429BR
<b>BRC48</b>			
Traction .....	PL8002		6944
<b>G36T1250N; G36T5011</b>			
Traction .....	PL8153		6947
<b>CARTER BROS. MFG.</b>			
<b>500-22 Series</b>			
Blade .....	M610		6835
<b>500-24 Series</b>			
Blade .....			6837
Drive .....	M308		6844
<b>700-22</b>			
Blade .....	M611		6935
Drive .....	M309		6842
<b>700-24</b>			
Blade .....	M613		6937
Drive .....	M309		6842
<b>H.W. E-Z MO</b>			
Drive .....	M308		6844
<b>CAUDLE MFG. CO</b>			
<b>35SPH; Star Clipper</b>			
Belt .....	540	1300	6730
<b>COAST TO COAST</b>			
<b>45-2029</b>			
Belt .....	7540252		6833
<b>120-270; 120-272; 121-282; 121-290;</b>			
<b>121-292; 122-250; 122-280; 122-290</b>			
Belt .....	7540114	2240	6824
<b>122-690; 122-692</b>			
Belt .....	7540239	2290	6829
<b>123-280; 123-290</b>			
Belt .....	7540114	2240	6824

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COAST TO COAST - Continued</b>			
<b>123-690</b>			
Belt .....	7540239	2290	6829
<b>124-224</b>			
Belt .....	7540242	2320	
<b>124-280; 124-290; 124-295; 338-2827;</b>			
<b>338-2835; 338-3122; 338-3130</b>			
Belt .....	7540114	2240	6824
<b>338-3320</b>			
Belt .....	7540239	2290	6829
<b>338-3338</b>			
Belt .....	7540114	2240	6824
<b>481-0248</b>			
Belt .....	7540252		6833
<b>481-0404</b>			
Belt; W/33" Belt O.C. ....	7540146	2330	6833
Belt; W/44" Belt O.C. ....	7540274	2440	6844
<b>481-0412; 481-0503; 481-0529</b>			
Belt .....	7540114	2240	6824
<b>481-0560</b>			
Belt .....	7540239	2290	6829
<b>481-1550</b>			
Belt .....	7540114	2240	6824
<b>481-1576</b>			
Belt .....	7540239	2290	6829
<b>481-2137</b>			
Belt .....	7540114	2240	6824
<b>481-2152; 481-2160</b>			
Drive .....	7540935		6831
<b>481-2186</b>			
Deck .....	7540109		6843
Drive .....	7540177		6832
<b>481-3572</b>			
Belt .....	1651020	2180	
<b>COLUMBIA PRODUCTS</b>			
<b>122-290</b>			
Belt .....	7540114	2240	6824
<b>122-343</b>			
Belt .....	7540252		6833
<b>122-550</b>			
Blade .....	7540177		6832
Drive .....	7540109		6843
<b>122-570</b>			
Blade .....	7540267		6859
<b>351-4</b>			
Belt .....	7540935	2310	6831
<b>551-3</b>			
Blade .....	7540109		6843
Drive .....	7540143		6728
<b>691-2; 691-3</b>			
Belt .....	7540239	2290	6829
<b>691-4</b>			
Belt .....	7540129	3440	6944
<b>697-2; 697-3</b>			
Belt .....	7540239	2290	6829
<b>COOPER</b>			
<b>110N22; 110N32; 118N12; 118N22; 120N22;</b>			
<b>120N32; 128N12; 128N22</b>			
Clutch .....		2240	6824
<b>CRUSADER</b>			
<b>C230</b>			
Traction .....	7540242		6832

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CRUSADER - Continued</b>			
<b>C270</b>			
Traction .....	7540114		6824
<b>CTL CORPORATION</b>			
<b>Frontrunner</b>			
Hydro .....			AX26
P.T.O. ....			AX35
<b>CUB CADET</b>			
<b>933E</b>			
Drive .....	1770334		6871BR
Eng. To Deck .....	1769767		6559BR
<b>4815F; 4816F</b>			
Deck .....	7543053		6781BR
P.T.O. ....	754-3066		6865BR
Pump .....	7540244		6840
<b>5418F</b>			
Deck .....	7543045		A120
P.T.O. ....	754-3066		6865BR
Pump .....	7540244		6840
<b>5521</b>			
Drive .....	01002700		6733
<b>CC 46</b>			
Drive .....	9540637A		6673BR
<b>CC 94; CC 98</b>			
Drive .....	9540460		6739
<b>CC 550</b>			
Drive .....	95404158		6460BR
<b>CC 600</b>			
Trans. ....	954-05090		6725
<b>CC 760; CC 800</b>			
P.T.O. ....	954-04139		6976BR
Trans. ....	95404145A		6864
<b>CC 949; CC 989; CC 997 ES</b>			
Drive .....	7540460		6739
<b>CC 999</b>			
Drive .....	9540460		6739
<b>G1236</b>			
Deck Drive .....	00050441		6573BR
Trans. ....	01000194		6844
Wheel Drive .....	01000151		6794BR
<b>G1332</b>			
Trans. ....	01000194		6844
Wheel Drive .....	01000151		6794BR
<b>G1548</b>			
Blade Drive .....	00050480		6864BR
P.T.O. ....	00021947		6614BR
Trans. ....	01000194		6844
Wheel Drive .....	01000151		6794BR
<b>G1752</b>			
Blade Drive .....	00068093		7040BR
P.T.O. ....	00068079		6816BR
Trans. ....	01000194		6844
Wheel Drive .....	01000151		6794BR
<b>H1536</b>			
Deck Drive .....	00050441		6573BR
Hydro. ....	01007579		6422BR
<b>H1748</b>			
Blade Drive .....	00050480		6864BR
Hydro. ....	01007333		7037BR
P.T.O. ....	00021947		6614BR
<b>H1952</b>			
Blade Drive .....	00068093		7040BR
Hydro. ....	01007579		6422BR
P.T.O. ....	00068079		6816BR
<b>Highwheel Rotary</b>			
Drive; W/26" Mower .....	7540326		6862

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CUB CADET - Continued</b>			
<b>SC 500 EQ</b>			
Drive .....	95404282		6731
<b>SC 700 E; SC 700 H</b>			
Front Drive .....	954-04259A		6734
Rear Drive .....	95404282		6731
<b>SC300 HW</b>			
Drive .....	954-04260		6734
<b>SC500 EZ; SC500 HW; SC500 Z</b>			
Drive .....	95404282		6731
<b>DEINES</b>			
<b>40-3TD; 48TD</b>			
Blade .....	400180		6898
Deck .....	400288		6866
<b>50TD</b>			
Blade .....	300601		A100
Deck .....	400288		6866
<b>60TD</b>			
Blade .....	400181		A136
Deck .....	300254		6862
<b>60TD-2</b>			
Blade .....	400945		6868
Deck .....	400288		6866
<b>72TD</b>			
Blade .....	400923		6876
Deck .....	400288		6866
<b>1400</b>			
Vacuum Attachment; W/40" Deck .....	400650		6831
Vacuum Attachment; W/50" Deck .....	200519		6835
<b>1800</b>			
Drive; W/60" Deck; W/68" Belt O.C. ....	400945		6868
Drive; W/66" Belt O.C. ....	400288		6866
Vacuum Attachment; W/40" Deck .....	400650		6831
Vacuum Attachment; W/48" Deck .....	400123		6840
Vacuum Attachment; W/50" Deck .....	200519		6835
<b>2000</b>			
Drive .....	400288		6866
Vacuum Attachment; W/48" Deck .....	400123		6840
<b>Dy-Na-Mo</b>			
Trans. ....	700123		6935
<b>Dy-Na-Mo 36</b>			
Blade .....	700136		6988
Drive .....	700123		6935
Traction .....	700105		6944
<b>Dy-Na-Mo 40</b>			
Deck; W/47" Belt O.C. ....	700509		6847
Deck; W/90" Belt O.C. ....	700508		6890
<b>Dy-Na-Mo 40-2</b>			
Blade; W/47" Belt O.C. ....	700509		6847
Blade; W/90" Belt O.C. ....	700508		6890
Drive .....	700123		6935
Traction .....	700105		6944
<b>Dy-Na-Mo 50</b>			
Blade .....	700531		6851
Deck .....	700532		6894
Drive .....	700123		6935
Traction .....	700105		6944
<b>DILLE &amp; MCGUIRE</b>			
<b>2418</b>			
Belt .....	BE118	2230	6823
<b>2424</b>			
Belt .....	11253	2440	6844
<b>2429</b>			
Belt .....	7591B	1360	6736
<b>A02100 Grassgroomer</b>			
Belt .....	BE118	2230	6823



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DILLE &amp; MCGUIRE - Continued</b>			
<b>HW22</b>			
Belt .....	9657B	2390	6839
<b>RPH21 Turfmaster; RPJ21 Turfmaster; RRH21 Turfmaster</b>			
Belt .....	BE118	2230	6823
<b>SPC22</b>			
Belt .....	BE112	2400	6840
<b>SPF22</b>			
Belt .....	7591B	1360	6736
<b>Turfmaster 21"</b>			
Belt .....	WM382	3230	6923
<b>Turfmaster King</b>			
Belt; W/18", 21" Deck .....	GRP82	1230	6723
Belt; W/22" Deck .....	BE112	2400	6840
<b>WM21; WMA21; WMB21; WMC21</b>			
Belt .....	WM382	3230	6923
<b>WMD21; WMD21D; WMD21R; WMF21; WMF21DS; WMG21DS; WMG21S</b>			
Belt .....		2170	6817
<b>DIXIE CHOPPER</b>			
<b>Pursuit 1832S</b>			
Trans. ....	200812		6834
<b>Pursuit 1836D</b>			
Eng. To Deck .....	301932		6968
Trans. ....	200869		6858
<b>Pursuit 1836S</b>			
Eng. To Deck .....	302030		6967
Trans. ....	200812		6834
<b>Pursuit 1844D</b>			
Deck Drive .....	301904		6434BR
Eng. To Deck .....	200864		6950
Trans. ....	200869		6858
<b>DIXON</b>			
<b>D149F22</b>			
Drive .....	532426609		6426BR
<b>D160H22</b>			
Drive .....	532406557		6671BR
<b>D190T22</b>			
Drive .....	532185476		6743
<b>ZTR 1001</b>			
Blade .....			69100
P.T.O. To Deck .....			6978
<b>DR POWER EQUIPMENT</b>			
<b>Premier Mower; Pro Mower; Pro-XL Mower</b>			
Drive .....	150061		A31
<b>Scout Mower</b>			
Deck Drive .....	114431		6845
Drive .....	150061		A31
<b>DURITE</b>			
<b>A22; N22</b>			
Belt .....		2250	6825
<b>S18</b>			
Belt .....		2300	6830
<b>S22</b>			
Belt .....		2250	6825
<b>SP22</b>			
Belt .....			6843
<b>SP24</b>			
Belt .....			6842
<b>SP36</b>			
Belt; W/46" Belt O.C. ....		2460	6846
Belt; W/53" Belt O.C. ....			6853

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DURITE - Continued</b>			
<b>SPV21</b>			
Belt; W/31" Belt O.C. ....		1310	6731
Belt; W/32" Belt O.C. ....		1320	6732
<b>DYNAMARK</b>			
<b>1105-0; 1105-00; 1105-1; 1105-01; 1105-02; 1105-03; 1105-04; 1105-05; 1105-06; 1105-07</b>			
Belt .....		2200	6820
<b>1105-08; 1105-09; 1105-10; 1105-11; 1105-12; 1105-13; 1105-14</b>			
Belt .....		2200	6820
<b>1115-0; 1115-02; 1115-03; 1115-04; 1115-07; 1115-08; 1115-09; 1115-10; 1115-11; 1115-12</b>			
Belt .....	LP2154	2200	6820
<b>1226-00; 1226-01; 1227-00; 1227-01; 1227-02</b>			
Belt .....	2363	2440	
<b>1227-03; 1227-04</b>			
Belt .....	3145	2230	6823
<b>1227-05; 1227-06; 1228-00; 1228-01; 1228-02; 1228-03; 1228-04</b>			
Belt .....	2363	2440	
<b>1229-01; 1230-00; 1230-01; 1230-02</b>			
Belt .....	20582	2430	6843
<b>1232-00; 1232-01; 1232-02</b>			
Belt .....	2363	2440	
<b>1243-00</b>			
Belt .....	42035	1400	6740
<b>1286-00</b>			
Belt .....	48530	1430	6743
<b>1288-03; 1288-04</b>			
Belt .....	2363	2440	
<b>1293-01</b>			
Blade .....	42881	3710	6971
Trans. ....	42858	2390	6839
<b>1299-00</b>			
Belt .....	48529	1450	6745
<b>2105-0; 2105-1; 2105-2; 2105-03; 2105-04; 2105-05; 2105-07; 2105-08; 2105-09; 2115-0</b>			
Belt .....		2200	6820
<b>2115-00</b>			
Belt .....	LP2154	2200	6820
<b>2115-1</b>			
Belt .....		2200	6820
<b>2115-01; 2115-02; 2115-03; 2115-04; 2115-05; 2115-06</b>			
Belt .....	LP2154	2200	6820
<b>2204</b>			
Drive; W/4 H.P. Eng. ....	53307	1430	6743
<b>2211-00; 2226-00; 2226-01; 2227-00; 2227-01; 2227-02; 2227-03; 2227-05; 2227-06</b>			
Belt .....	2363	2440	
<b>4106-00; 4106-02; 4108-00; 4108-01; 4120-00; 4121-00; 4124-00; 4124-01</b>			
Belt .....		2240	6824
<b>4218-00; 4218-01; 4218-02; 4228-00; 4228-02; 4228-04; 4228-06; 4228-08; 4229-00</b>			
Belt .....	2363	2440	
<b>4265-08; 4265-09</b>			
Belt .....	42035	1400	6740
<b>5036-00; 5036-01; 5036-03</b>			
Belt .....	8597	2220	6822
<b>5100-01</b>			
Belt .....		2200	6820

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
5105-00; 5105-01; 5105-02; 5105-03; 5105-04; 5105-05 Belt .....	LP383	2240	6824
5105-07 Belt .....		2230	6823
5105-08 Belt .....	LP383	2240	6824
5105-09 Belt .....		2230	6823
5105-11 Belt .....	8597	2220	6822
5105-12 Belt .....	LP383	2240	6824
5105-13; 5105-14; 5105-15 Belt .....	8597	2220	6822
5105-16; 5105-18; 5105-21; 5105-22; 5105-30 Belt .....	LP383	2240	6824
5105-31 Belt .....	8597	2220	6822
5105-33; 5105-34; 5105-35; 5105-36; 5105-37; 5105-38; 5105-40 Belt .....	LP383	2240	6824
5105-41 Belt .....		2230	6823
5105-42 Belt .....	LP383	2240	6824
5105-44; 5105-50; 5105-55; 5105-57 Belt .....		2230	6823
5105-59 Belt .....	8597	2220	6822
5105-60; 5105-65; 5105-67 Belt .....		2230	6823
5105-71 Belt .....	8597	2220	6822
5105-73 Belt .....	LP383	2240	6824
5107-01; 5107-02; 5107-04; 5108-00; 5108-32 Belt .....		2200	6820
5110-00; 5110-01 Belt .....		2240	6824
5111-30; 5111-33 Belt .....		2200	6820
5115-00; 5115-01 Belt .....	8597	2220	6822
5120-00; 5120-01; 5120-03; 5120-58 Belt .....		2240	6824
5121-02; 5121-04; 5121-30 Belt .....	8597	2220	6822
5121-55 Belt .....		2230	6823
5121-56; 5121-58 Belt .....	8597	2220	6822
5222-00; 5222-30; 5222-31; 5222-32; 5222-34; 5222-36; 5222-38; 5222-40; 5223-01; 5223-05 Belt .....	2363	2440	
5223-07; 5223-30; 5223-31; 5223-32; 5223-38; 5223-39; 5223-43; 5223-45; 5223-49 Belt .....	2363	2440	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
5227-00; 5227-01; 5227-03; 5227-05; 5227-07; 5227-09; 5227-11; 5227-31; 5227-41; 5227-43 Belt .....	20582	2430	6843
5227-45; 5227-47; 5227-51; 5227-53; 5227-55 Belt .....	20582	2430	6843
5230-00; 5230-01; 5231-01; 5231-10; 5231-16; 5231-41; 5231-51; 5231-61 Belt .....	2363	2440	
5265-01; 5265-03; 5265-04; 5265-05; 5265-06; 5265-07; 5265-10; 5265-11; 5265-12; 5265-13 Belt .....	42035	1400	6740
5265-14; 5265-15 Belt .....	42035	1400	6740
5298-50; 5298-51; 5298-53 Belt .....	48529	1450	6745
5298-64; 5298-65; 5298-66; 5298-67; 5298-68 Traction .....	52450	1290	6729
5302-00; 5302-01 Belt .....	48529	1450	6745
8158; 8196; 9120; 9121 Belt .....		2240	6824
50254 Belt .....	2363	2440	
50304 Traction .....		2230	6823
50304A; 50314; 50316-00; 50316-01 Belt .....	8597	2220	6822
11010000 Drive .....			6826
42180000; 42180100; 42180200; 42280000; 42280400; 42280600; 42280800; 42290000; 52220000; 52223000 Belt .....	2363	2440	
CB520A; CB520B Belt .....		2200	6820
CH422A; CH422B; CH422C Belt .....	2363	2440	
LP420; LP430; LP430A; LP430B; LP430C; LP430D Belt .....		2200	6820
RA222; SP22A; SP22B; XPO225; XPT225 Belt .....	2363	2440	
<b>EDKO</b>			
Lawn Mowers			
Blade .....	20825		B63
Trans. ....		2300	6830
<b>ENCORE</b>			
32B100; 32B100E; 32K200			
Blade Drive .....	323003		6647BR
Trans. ....	363212		7025BR
Wheel Drive .....	363312		6809BR
32K250			
Blade Drive .....	323003		6647BR
Pump Drive .....	363212		7025BR
36B100; 36B100E; 36K200			
Blade .....	363210		6573BR
Drive .....	363312		6809BR
Trans. ....	363212		7025BR
36K250; 36K450			
Blade .....	363210		6573BR
Drive .....	363212		7025BR





Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ENCORE - Continued</b>				<b>ENCORE - Continued</b>			
<b>48B300; 48B300E</b>				<b>60K400 - Continued</b>			
Blade .....	483030		6614BR	Right Angle Drive .....	603016		6854BR
Drive .....	363312		6809BR	Trans. ....	363212		7025BR
Right Angle Drive .....	483031		6864BR				
Trans. ....	363212		7025BR	<b>60K450; 60K550E</b>			
<b>48B350EWT; 48B350WT; 48B450EWT;</b>				Blade .....	603015		6480BR
<b>48B450WT</b>				Drive .....	363212		7025BR
Blade .....	483030		6614BR	Right Angle Drive .....	603016		6854BR
Drive .....	363212		7025BR				
Right Angle Drive .....	483031		6864BR	<b>EW32FS481V</b>			
<b>48K200</b>				Blade Drive .....	323003		6647BR
Blade .....	483030		6614BR	Trans. ....	363212		7025BR
Drive .....	363312		6809BR	Wheel Drive .....	363312		Ⓜ6809BR
Right Angle Drive .....	483031		6864BR				
Trans. ....	363212		7025BR	<b>EW36FS481V</b>			
<b>48K250WT</b>				Blade Drive .....	363210		6573BR
Blade .....	483030		6614BR	Trans. ....	363212		7025BR
Drive .....	363212		7025BR	Wheel Drive .....	363312		Ⓜ6809BR
Right Angle Drive .....	483031		6864BR				
<b>48K400</b>				<b>EW36FS481VH</b>			
Blade .....	483030		6614BR	Blade Drive .....	363210		6573BR
Drive .....	363312		6809BR				
Right Angle Drive .....	483031		6864BR	<b>EW48FS481V</b>			
Trans. ....	363212		7025BR	Blade - Right .....	483031		6864BR
<b>48K450EWT; 48K450WT; 48K550EWT</b>				Blade Drive .....	483030		6614BR
Blade .....	483030		6614BR	Trans. ....	363212		7025BR
Drive .....	363212		7025BR	Wheel Drive .....	363312		Ⓜ6809BR
Right Angle Drive .....	483031		6864BR				
<b>48T200</b>				<b>EW48FS481VH</b>			
Blade .....	483030		6614BR	Blade - Right .....	483031		6864BR
Drive .....	363312		6809BR	Blade Drive .....	483030		6614BR
Right Angle Drive .....	483031		6864BR	Trans. ....	363212		7025BR
Trans. ....	363212		7025BR	Wheel Drive .....	363312		Ⓜ6809BR
<b>52B300; 52B300E</b>							
Drive .....	363312		6809BR	<b>WB32K13; WB32K16</b>			
Trans. ....	363212		7025BR	Deck Drive .....	323003		6647BR
<b>52B350; 52B350E</b>				Drive .....	363312		6809BR
Drive .....	363212		7025BR	Trans. ....	363212		7025BR
<b>52B400; 52B400E</b>							
Drive .....	363312		6809BR	<b>WB36K13</b>			
Trans. ....	363212		7025BR	Deck Drive .....	363210		6573BR
<b>52B450; 52B450E</b>				Drive .....	363312		6809BR
Drive .....	363212		7025BR	Trans. ....	363212		7025BR
<b>52K200; 52K400</b>							
Drive .....	363312		6809BR	<b>WB36K13H</b>			
Trans. ....	363212		7025BR	Deck Drive .....	363210		6573BR
<b>52K450; 52K450E; 52K550E</b>				Hydro. Drive .....	363212		7025BR
Drive .....	363212		7025BR				
<b>60B300; 60B300E</b>				<b>WB36K16</b>			
Blade .....	603015		6480BR	Deck Drive .....	363210		6573BR
Drive .....	363312		6809BR	Drive .....	363312		6809BR
Right Angle Drive .....	603016		6854BR	Trans. ....	363212		7025BR
Trans. ....	363212		7025BR				
<b>60B350; 60B350E</b>				<b>WB36K16H</b>			
Blade .....	603015		6480BR	Deck Drive .....	363210		6573BR
Drive .....	363212		7025BR	Hydro. Drive .....	363212		7025BR
Right Angle Drive .....	603016		6854BR				
<b>60B400; 60B400E</b>				<b>WB48K16</b>			
Blade .....	603015		6480BR	Blade - Right .....	483031		6864BR
Drive .....	363312		6809BR	Blade Drive .....	483030		6614BR
Right Angle Drive .....	603016		6854BR	Drive .....	363312		6809BR
Trans. ....	363212		7025BR	Trans. ....	363212		7025BR
<b>60B450; 60B450E</b>							
Blade .....	603015		6480BR	<b>WB48K16H</b>			
Drive .....	363212		7025BR	Blade - Right .....	483031		6864BR
Right Angle Drive .....	603016		6854BR	Blade Drive .....	483030		6614BR
<b>60K400</b>				Hydro. Drive .....	363212		7025BR
Blade .....	603015		6480BR				
Drive .....	363312		6809BR	<b>WB48K17</b>			
				Deck Drive .....	483030		6614BR
				Drive .....	363312		6809BR
				Trans. ....	363212		7025BR
				<b>WB48K17H</b>			
				Deck Drive .....	483030		6614BR
				Hydro. Drive .....	363212		7025BR
				<b>ESKA</b>			
				<b>1504 22" S.P.</b>			
				Belt .....	80006	1260	6726
				<b>1625</b>			
				Eng. To Transaxle .....	80015		6879
				Mower Pan To Blade; W/28" Belt O.C. ....	80014	2280	6828
				Mower Pan To Blade; W/30" Belt O.C. ....	80012	2300	6830
				<b>1625A</b>			
				Mower Pan To Blade .....	80017	2280	6828

ⓂTwo Required

# WALK BEHIND MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ESKA - Continued</b>			
<b>1626A; 1626B; 1626E</b>			
Mower Pan To Blade; W/28" Belt O.C. ....	80017	2280	6828
Mower Pan To Blade; W/30" Belt O.C. ....	80018	2300	6830
<b>Mark 26 (1601)</b>			
Blade .....	80009	2820	6882
Transaxle .....	80010	2680	6868
Variable Speed .....	80011	2180	6818
<b>EVERRIDE</b>			
<b>EGWKA1332S</b>			
Deck Drive .....	07200502		6976
Traction .....	07400037		7124BR
Trans. ....	07225500		6948BR
<b>EGWKA1336S</b>			
Deck Drive .....	00201010		6815BR
Traction .....	07400037		7124BR
Trans. ....	07225500		6948BR
<b>EGWKA1548S</b>			
Blade .....	D38019		6993BR
Eng. To Deck .....	07200504		6866BR
Traction .....	07400037		7124BR
Trans. ....	07225500		6948BR
<b>EHWKA1536S</b>			
Deck Drive .....	D38007		6402BR
Trans. ....	D38006		6820BR
<b>EHWKA1948S</b>			
Blade .....	D38019		6993BR
Eng. To Deck .....	D18087		6555BR
Trans. ....	D38006		6820BR
<b>EHWKA1952S</b>			
Deck Drive .....	TCU18848		6492BR
Trans. ....	D38006		6820BR
<b>ELKW1748S</b>			
Blade .....	D38019		6993BR
Eng. To Deck .....	D18087		6555BR
Trans. ....	D38006		6820BR
<b>EXMARK</b>			
<b>21" S.P.</b>			
Drive; W/29" Belt O.C.; Ser. No. 10,000 & After .....	213076		6829
Drive; W/37" Belt O.C.; Ser. No. 10,000 & After .....	213077		6837
<b>32"</b>			
Deck .....	323017		7068BR
Trans.; W/5-Speed Drive .....	403018		6937
Trans.; W/Variable Speed Drive .....	303078		6936
Wheel Drive; W/5-Speed Drive .....	323051		6423BR
Wheel Drive; W/Variable Speed Drive .....	303079		6429BR
<b>32" 5-Speed</b>			
Deck Drive .....	323017		7068BR
Trans. ....	403018		6937
Wheel Drive .....	323051		6423BR
<b>32" Variable</b>			
Deck Drive .....	323017		7068BR
Trans. ....	303078		6936
Wheel Drive .....	303079		6429BR
<b>36"</b>			
Deck .....	303080		6614BR
Trans.; W/5-Speed Drive .....	403018		6937
Trans.; W/Variable Speed Drive .....	303078		6936
Wheel Drive; W/5-Speed Drive .....	323051		6423BR
Wheel Drive; W/Variable Speed Drive .....	303079		6429BR
<b>36" 5-Speed</b>			
Deck .....	303080		6614BR
Trans. ....	403018		6937
Wheel Drive .....	323051		6423BR
<b>36" Variable</b>			
Deck .....	303080		6614BR
Trans. ....	303078		6936
Wheel Drive .....	303079		6429BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>36-11H</b>			
Belt .....	303080A		6989
<b>48"</b>			
Cross Deck .....	403025		6446BR
Deck Drive .....	403024		6877BR
Trans.; W/5-Speed Drive .....	403018		6937
Trans.; W/Variable Speed Drive .....	303078		6936
Wheel Drive; W/5-Speed Drive .....	323051		6423BR
Wheel Drive; W/Variable Speed Drive .....	303079		6429BR
<b>48" 5-Speed</b>			
Cross Deck .....	403025		6446BR
Deck Drive .....	403024		6877BR
Trans. ....	403018		6937
Wheel Drive .....	323051		6423BR
<b>48" Variable</b>			
Cross Deck .....	403025		6446BR
Deck Drive .....	403024		6877BR
Trans. ....	303078		6936
Wheel Drive .....	303079		6429BR
<b>ECKA30; ECS180CKA30000</b>			
Lower Drive .....	116-7116		7003BR
Upper Drive .....	121-5765		6453BR
<b>ECS180GKA21000; ECSHN21; ECSKA21; ECX160CHN21000</b>			
Drive .....	109-7299		6736
<b>ECX180CKA210BC</b>			
Blade Drive .....	110-1790		6822
Drive .....	109-7299		6736
<b>ECX180CKA21000; ECXHN21</b>			
Drive .....	109-7299		6736
<b>ECXHNBBBC21</b>			
Blade Drive .....	110-1790		6822
Drive .....	109-7299		6736
<b>ECXKA21</b>			
Drive .....	109-7299		6736
<b>ECXKABBC21</b>			
Blade Drive .....	110-1790		6822
Drive .....	109-7299		6736
<b>M15KA322P</b>			
Eng. To Blade; W/32" Deck .....	1-323734		6506BR
Eng. To Trans. ....	323280		6840
Traction .....	323344		6487BR
<b>M15KA362; M15KA362P</b>			
Blade Drive .....	1-323733		6573BR
Traction .....	1-323288		6586BR
Trans. ....	1-323280		6840
<b>M15KA483; M15KA483P</b>			
Blade Drive .....	1-403174		6665BR
Traction .....	1-323288		6586BR
Trans. ....	1-323280		6840
<b>M16KA322P</b>			
Blade Drive .....	1-323734		6506BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323344		6487BR
<b>M16KA362; M16KA362P</b>			
Blade Drive .....	1-323733		6573BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323288		6586BR
<b>M16KA483; M16KA483P</b>			
Blade Drive .....	1-403174		6665BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323288		6586BR
<b>M216KA; M216KASP; M216KASPC</b>			
Drive .....	213237		6734
<b>M3211B; M3213KA</b>			
Blade Drive; Ser. No. 220000 & Before ...	323345		6981
Blade Drive; Ser. No. 220001 & After .....	323734		6506BR
Trans. ....	323280		6840



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>M3211B; M3213KA – Continued</b>			
Wheel Drive .....	323344		6487BR
<b>M3613KA; M3613KC; M3615KA</b>			
Blade Drive; Ser. No. 220000 & Before .....	323299		6812BR
Blade Drive; Ser. No. 220001 & After .....	323733		6573BR
Trans. ....	323280		6840
Wheel Drive .....	323288		6586BR
<b>M4815KA</b>			
Blade - Right; Ser. No. 220000 & Before ..	403025		6446BR
Blade Drive; Ser. No. 220000 & Before ....	403174		6665BR
Blade Drive; Ser. No. 220001 & After .....	323300		6591BR
Trans. ....	323280		6840
Wheel Drive .....	323288		6586BR
<b>M4815KC; M4817KA</b>			
Blade Drive; Ser. No. 220000 & Before ....	403174		6665BR
Blade Drive; Ser. No. 220001 & After .....	323300		6591BR
Drive - Right .....	403025		6446BR
Trans. ....	323280		6840
Wheel Drive .....	323288		6586BR
<b>Metro 5-Speed</b>			
Right Side Blade Drive; W/48" Deck .....	403025		6446BR
<b>MG16KA322P</b>			
Deck Drive .....	1-323734		6506BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323344		6487BR
<b>MG16KA362; MG16KA362P</b>			
Deck Drive .....	1-323733		6573BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323288		6586BR
<b>MG16KA483; MG16KA483P</b>			
Deck Drive .....	1-403174		6665BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323288		6586BR
<b>MG481KA322P</b>			
Deck Drive .....	1-323734		6506BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323344		6487BR
<b>MG481KA362; MG481KA362P</b>			
Deck Drive .....	1-323733		6573BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323288		6586BR
<b>MG481KA483; MG481KA483P</b>			
Deck Drive .....	1-403174		6665BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323288		6586BR
<b>MGS481CKA36200</b>			
Deck Drive .....	1-323733		6573BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323288		6586BR
<b>MGS481CKA48300</b>			
Deck Drive .....	1-403174		6665BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323288		6586BR
<b>MGS481GKA322P0</b>			
Deck Drive .....	1-323734		6506BR
Trans. ....	1-323280		6840
Wheel Drive .....	1-323344		6487BR
<b>MHP3615KA; MHP3615KC</b>			
Blade Clutch .....	413096		6936
Deck Drive .....	413094		6917BR
Trans. ....	323280		6840
Wheel Drive .....	413341		7018BR
<b>MHP4815KA; MHP4815KC; MHP4817KA</b>			
Blade Clutch .....	413096		6936
Deck Drive .....	413093		6596BR
Trans. ....	323280		6840
Wheel Drive .....	413341		7018BR
<b>MHP5217KA</b>			
Blade Clutch .....	413096		6936
Deck Drive .....	413308		6783BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>MHP5217KA – Continued</b>			
Trans. ....	323280		6840
Wheel Drive .....	413341		7018BR
<b>MS6KA26B; MSKABBC26</b>			
Blade Drive .....	116-0823		6930
Traction .....	103-6114		6726
<b>Standard 5-Speed</b>			
Cross Deck; W/48" Deck .....	403025		6446BR
Deck; W/32" Deck .....	323017		7068BR
Deck; W/36" Deck .....	303080		6614BR
Deck; W/48" Deck .....	403024		6877BR
Trans. ....	403018		6937
Wheel Drive .....	323051		6423BR
<b>THP15KA363</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After ....	103-6317		B35
Deck Drive; W/36" Deck .....	413094		6917BR
Pump Drive .....	413095		6685BR
<b>THP16KA363</b>			
Blade Clutch .....	103-6317		B35
Deck Drive .....	1-413094		6917BR
Hydro. Drive .....	109-1057		6685BR
<b>THP16KA483</b>			
Blade Clutch .....	103-6317		B35
Deck Drive .....	1-413093		6596BR
Hydro. Drive .....	109-1057		6685BR
<b>THP17KA483</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After ....	103-6317		B35
Deck Drive; W/48" Deck .....	413093		6596BR
Pump Drive .....	413095		6685BR
<b>THP17KA523</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After ....	103-6317		B35
Deck Drive; W/52" Deck .....	413308		6783BR
Pump Drive .....	413095		6685BR
<b>THP18KAE523</b>			
Blade Clutch .....	103-6317		B35
Deck Drive .....	1-413308		6783BR
Hydro. Drive .....	109-1057		6685BR
<b>THP19KAE483</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After ....	103-6317		B35
Deck Drive; W/48" Deck .....	413093		6596BR
Pump Drive .....	413095		6685BR
<b>THP19KAE523</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After ....	103-6317		B35
Deck Drive; W/52" Deck .....	413308		6783BR
Pump Drive .....	413095		6685BR
<b>THP20KAE483</b>			
Blade Clutch .....	103-6317		B35
Deck Drive .....	1-413093		6596BR
Hydro. Drive .....	109-1057		6685BR
<b>THP20KAE523</b>			
Blade Clutch .....	103-6317		B35
Deck Drive .....	1-413308		6783BR
Hydro. Drive .....	109-1057		6685BR
<b>TT19KA</b>			
Cross Deck; W/FMD-52, FMD-523 Deck ..	603576		6480BR
Cross Deck; W/FMD-60, FMD-603 Deck ..	603045		6928BR
Eng. To Deck; W/FMD52 Deck; Ser. No. 83999 & Before .....	603582		6866BR
Eng. To Deck; W/FMD-52, FMD-523 Deck; Ser. No. 84000 & After .....	603306		6506BR
Eng. To Deck; W/FMD-60, FMD-603 Deck .....	603306		6506BR
Pump Drive; W/52", 60" Deck .....	603809		6959
<b>TT20KCC</b>			
Pump Drive .....	413095		6685BR

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>TT20KCE Hydro</b>			
Blade Drive; W/52" Deck .....	103-2329		6480BR
Blade Drive; W/60" Deck .....	1-633173		6650BR
Eng. To Deck; W/52" Deck .....	103-2240		6754BR
Eng. To Deck; W/60" Deck .....	1-603306		6506BR
Pump .....	109-2584		6886BR
<b>TT23KA Hydro; TT23KAC</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After .....	103-6317		B35
Blade Drive; W/36" Deck .....	413094		6917BR
Blade Drive; W/48" Deck .....	413093		6596BR
Blade Drive; W/52" Deck .....	413308		6783BR
Pump Drive .....	413095		6685BR
<b>TT23KAE Hydro</b>			
Blade Drive; W/52" Deck .....	103-2329		6480BR
Blade Drive; W/60" Deck .....	1-633173		6650BR
Eng. To Deck; W/52" Deck .....	103-2240		6754BR
Eng. To Deck; W/60" Deck .....	1-603306		6506BR
Pump .....	109-2584		6886BR
<b>TT23KC</b>			
Cross Deck; W/FMD-52, FMD-523 Deck	603576		6480BR
Cross Deck; W/FMD-60, FMD-603 Deck	603045		6928BR
Eng. To Deck; W/FMD52 Deck; Ser. No. 83999 & Before .....	603582		6866BR
Eng. To Deck; W/FMD-52, FMD-523 Deck; Ser. No. 84000 & After .....	603306		6506BR
Eng. To Deck; W/FMD-60, FMD-603 Deck .....	603306		6506BR
Pump .....	603809		6959
<b>TT23KCC</b>			
Pump Drive .....	413095		6685BR
<b>TT24KAE</b>			
Blade Drive; W/52" Deck .....	103-2329		6480BR
Blade Drive; W/60" Deck .....	1-633173		6650BR
Eng. To Deck; W/52" Deck .....	103-2240		6754BR
Eng. To Deck; W/60" Deck .....	1-603306		6506BR
Hydro. Drive .....	109-2584		6886BR
<b>TT3615KA</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After .....	103-6317		B35
Deck Drive .....	413094		6917BR
Pump Drive .....	413095		6850
<b>TT3615KA HP; TT3615KAC</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After .....	103-6317		B35
Deck Drive; W/36" Deck .....	413094		6917BR
Pump Drive .....	413095		6685BR
<b>TT3615KAC HP-ECS</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After .....	103-6317		B35
Deck Drive; W/36" Drive .....	413094		6917BR
Pump Drive .....	413095		6685BR
<b>TT4815KA; TT4815KC; TT4817KA</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After .....	103-6317		B35
Deck Drive .....	413093		6596BR
Pump Drive .....	413095		6850
<b>TT4817KA HP; TT4817KAC; TT4817KAC HP-ECS</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After .....	103-6317		B35
Deck Drive .....	413093		6596BR
Pump Drive .....	413095		6685BR
<b>TT4817KAE</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After .....	103-6317		B35
Deck Drive .....	413093		6596BR
Pump Drive .....	413095		6850
<b>TT4817KAE HP; TT4817KAE; TT4817KAE HP-ECS</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After .....	103-6317		B35

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>TT4817KAE HP; TT4817KAE; TT4817KAE HP-ECS - Continued</b>			
Deck Drive .....	413093		6596BR
Pump Drive .....	413095		6685BR
<b>TT5217KA</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Drive; Ser. No. 510000 & After .....	103-6317		B35
Deck Drive .....	413308		6783BR
Pump Drive .....	413095		6850
<b>TT5217KA HP; TT5217KAC; TT5217KAC HP-ECS; TT5217KAE; TT5217KAE HP-ECS</b>			
Blade Clutch; Ser. No. 509999 & Before ..	413096		6936
Blade Clutch; Ser. No. 510000 & After .....	103-6317		B35
Deck Drive .....	413308		6783BR
Pump Drive .....	413095		6685BR
<b>TTS16KA363</b>			
Blade Drive .....	1-413094		6917BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS16KA483</b>			
Blade Drive .....	1-413093		6596BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS18KA523</b>			
Blade Drive .....	1-413308		6783BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS20KAE483</b>			
Blade Drive .....	1-413093		6596BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS20KAE523</b>			
Blade Drive .....	1-413308		6783BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS20PKAE483</b>			
Blade Drive .....	1-413093		6596BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS20PKAE523</b>			
Blade Drive .....	1-413308		6783BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS481CKA36300</b>			
Hydro. Drive .....	103-4761		6726BR
<b>TTS481GKA48300</b>			
Deck Drive .....	126-0783		6982BR
Hydro. Drive .....	103-4761		6726BR
<b>TTS481KA363</b>			
Blade Drive .....	1-413094		6917BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS481KA483</b>			
Blade Drive .....	1-413093		6596BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS541GKA52300</b>			
Hydro. Drive .....	103-4761		6726BR
<b>TTS541KA523</b>			
Blade Drive .....	1-413308		6783BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS600GKA483E0</b>			
Deck Drive .....	126-0783		6982BR
Hydro. Drive .....	103-4761		6726BR
<b>TTS600GKA523E0</b>			
Hydro. Drive .....	103-4761		6726BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>TTS600KAE483</b>			
Blade Drive .....	1-413093		6596BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS600KAE523</b>			
Blade Drive .....	1-413308		6783BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS600PKAE483</b>			
Blade Drive .....	1-413093		6596BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTS680PKC483E0</b>			
Deck Drive .....	126-0783		6982BR
Hydro. Drive .....	103-4761		6726BR
<b>TTS680PKCE483</b>			
Blade Drive .....	1-413093		6596BR
Eng. To Deck .....	103-6317		B35
Hydro. Drive .....	109-1057		6685BR
<b>TTX20KCE; TTX21EKCE; TTX24KAE; TTX24PKAE; TTX640KCE</b>			
Blade Drive; W/52" Deck .....	103-2329		6480BR
Blade Drive; W/60" Deck .....	1-633173		6650BR
Eng. To Deck; W/52" Deck .....	103-2240		6754BR
Eng. To Deck; W/60" Deck .....	1-603306		6506BR
Hydro. Drive .....	109-2584		6886BR
<b>TTX650EKC604N0</b>			
Hydro. Drive .....	103-4761		6726BR
<b>TTX650EKC52400</b>			
Deck Drive .....	126-2538		6853BR
Hydro. Drive .....	103-4761		6726BR
<b>TTX650EKC60400</b>			
Hydro. Drive .....	103-4761		6726BR
<b>TTX650EKCE</b>			
Blade Drive; W/52" Deck .....	103-2329		6480BR
Blade Drive; W/60" Deck .....	1-633173		6650BR
Eng. To Deck; W/52" Deck .....	103-2240		6754BR
Eng. To Deck; W/60" Deck .....	1-603306		6506BR
Hydro. Drive .....	109-2584		6886BR
<b>TTX650EKCE524</b>			
Blade Drive .....	103-2329		6480BR
Eng. To Deck .....	103-2240		6754BR
Hydro. Drive .....	109-2584		6886BR
<b>TTX650EKCE604; TTX650EKCE604N</b>			
Blade Drive .....	1-633173		6650BR
Eng. To Deck .....	1-603306		6506BR
Hydro. Drive .....	109-2584		6886BR
<b>TTX680PKC52400</b>			
Deck Drive .....	126-2538		6853BR
Hydro. Drive .....	103-4761		6726BR
<b>TTX680PKC60400</b>			
Hydro. Drive .....	103-4761		6726BR
<b>TTX680PKCE524</b>			
Blade Drive .....	103-2329		6480BR
Eng. To Deck .....	103-2240		6754BR
Hydro. Drive .....	109-2584		6886BR
<b>TTX680PKCE604</b>			
Blade Drive .....	1-633173		6650BR
Eng. To Deck .....	1-603306		6506BR
Hydro. Drive .....	109-2584		6886BR
<b>TTX691KAE</b>			
Blade Drive; W/52" Deck .....	103-2329		6480BR
Blade Drive; W/60" Deck .....	1-633173		6650BR
Eng. To Deck; W/52" Deck .....	103-2240		6754BR
Eng. To Deck; W/60" Deck .....	1-603306		6506BR
Hydro. Drive .....	109-2584		6886BR
<b>TTX691KAE524</b>			
Blade Drive .....	103-2329		6480BR
Eng. To Deck .....	103-2240		6754BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>TTX691KAE524 - Continued</b>			
Hydro. Drive .....	109-2584		6886BR
<b>TTX691KAE604</b>			
Blade Drive .....	1-633173		6650BR
Eng. To Deck .....	1-603306		6506BR
Hydro. Drive .....	109-2584		6886BR
<b>TTX691PKAE</b>			
Blade Drive; W/52" Deck .....	103-2329		6480BR
Blade Drive; W/60" Deck .....	1-633173		6650BR
Eng. To Deck; W/52" Deck .....	103-2240		6754BR
Eng. To Deck; W/60" Deck .....	1-603306		6506BR
Hydro. Drive .....	109-2584		6886BR
<b>Turf Ranger</b>			
Blade Drive; W/52" Deck; Ser. No. 319999 & Before .....	603576		6480BR
Blade Drive; W/52" Deck; Ser. No. 320000 & After .....	103-2329		6480BR
Blade Drive; W/60" Deck; Ser. No. 319999 & Before .....	603045		6928BR
Blade Drive; W/60" Deck; Ser. No. 320000 & After .....	633173		6650BR
Deck; W/52" Deck; Ser. No. 115000 & After .....	543749		6649BR
Deck; W/60" Deck; Ser. No. 90000- 114999 .....	323300		6591BR
Deck Drive; W/52" Deck; Ser. No. 83999 & Before .....	543898		6991
Deck Drive; W/52" Deck; Ser. No. 84000-114999 .....	543028		6649BR
Deck Drive; W/60" Deck; Ser. No. 115000 & After .....	543523		6839BR
Deck Drive; W/60" Deck; Ser. No. 89999 & Before .....	543521		6987
Trans. ....	543548		6837
<b>Variable Speed</b>			
Cross Deck; W/48" Deck .....	403025		6446BR
Deck; W/32" Deck .....	323017		7068BR
Deck; W/36" Deck .....	303080		6614BR
Deck; W/48" Deck .....	403024		6877BR
Trans. ....	303078		6936
Wheel Drive .....	303079		6429BR
<b>VH15KA362</b>			
Deck Drive .....	1-323735		6754BR
Pump .....	103-4760		6726BR
<b>VH15KA483</b>			
Deck Drive .....	1-403174		6665BR
Pump .....	103-4760		6726BR
<b>VH16KA362</b>			
Deck Drive .....	1-323735		6754BR
Hydro. Drive .....	103-4760		6726BR
<b>VH16KA483</b>			
Deck Drive .....	1-403174		6665BR
Hydro. Drive .....	103-4760		6726BR
<b>VH481KA362</b>			
Deck Drive .....	1-323735		6754BR
Hydro. Drive .....	103-4760		6726BR
<b>VH481KA483</b>			
Deck Drive .....	1-403174		6665BR
Hydro. Drive .....	103-4760		6726BR
<b>VH3615KA</b>			
Eng. To Deck; Ser. No. 220000 & Before .....	323200		6754BR
Eng. To Deck; Ser. No. 220001 & After ...	323735		6754BR
Pump; Ser. No. 220000 & Before .....	323225		6822BR
Pump Drive; Ser. No. 220001 & After .....	653163		6726BR
<b>VH4815KA</b>			
Blade - Right; Ser. No. 220000 & Before .	403025		6446BR
Eng. To Deck; Ser. No. 220000 & Before .....	303499		6649BR
Eng. To Deck; Ser. No. 220001 & After ...	403174		6665BR
Pump Drive; Ser. No. 220000 & Before ...	323225		6822BR
Pump Drive; Ser. No. 220001 & After .....	653163		6726BR

Lawn & Garden Equipment



**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>VHS481GKA36200</b>			
Deck Drive .....	1-323735		6754BR
Hydro. Drive .....	103-4760		6726BR
<b>VHS481GKA48300</b>			
Deck Drive .....	1-403174		6665BR
Hydro. Drive .....	103-4760		6726BR
<b>Viking; Viking 5-Speed; Viking Hydro</b>			
Cross Deck; W/48" Deck .....	403025		6446BR
Deck; W/32" Deck .....	323017		7068BR
Deck; W/36" Deck .....	303080		6614BR
Deck; W/48" Deck .....	403024		6877BR
Trans. ....	403018		6937
Wheel Drive .....	323051		6423BR
<b>VT20KAS484</b>			
Deck Drive .....	99-4627		6767BR
Hydro. Drive .....	114567		6927BR
<b>VT20KAS524</b>			
Deck Drive .....	116-3111		6598BR
Hydro. Drive .....	114567		6927BR
<b>VT24KAS484</b>			
Deck Drive .....	99-4627		6767BR
Hydro. Drive .....	114567		6927BR
<b>VT24KAS524</b>			
Deck Drive .....	116-3111		6598BR
Hydro. Drive .....	114567		6927BR
<b>FALLS</b>			
<b>22-119; 22-132; 22-137; 22-142; 22-146; 22-159</b>			
Belt .....	152160	1380	6738
<b>BP21; F2100; F2100R</b>			
Belt .....	151360	2290	6829
<b>H25 25" Push</b>			
Belt .....	152920	2600	6860
<b>H256 25" Push</b>			
Belt .....	153030	2540	6854
<b>H2500</b>			
Eng. To Gear Box .....	152980	2360	6836
Eng. To Spindle .....	152920	2600	6860
<b>R2200</b>			
Belt .....	151370	2275	
<b>R2500</b>			
Belt .....	152880	2340	6834
<b>RP22; RP22R; SP22</b>			
Belt .....	151670	1360	6736
<b>FERRIS INDUSTRIES, INC.</b>			
<b>BGF48KA; BGF48KAV15</b>			
Deck Drive .....	5021297		6752BR
<b>BGF52KA; BGF52KAV15</b>			
Deck Drive .....	5021854		6946BR
<b>CCWKAV1536</b>			
Deck Drive; W/Rear Discharge .....	5101313		6702BR
Eng. To Deck; W/Side Discharge .....	5101508		6482BR
<b>CCWKAV1948</b>			
Deck Drive .....	5100814		6567BR
Pump .....	5022173		6743BR
<b>CCWKAV1952</b>			
Deck Drive .....	5022435		6933BR
Pump .....	5022173		6743BR
<b>CCWKAV2148</b>			
Deck Drive .....	5100814		6567BR
Pump .....	5022173		6743BR
<b>CCWKAV2152; CCWKAV2452</b>			
Deck Drive .....	5022435		6933BR
Pump .....	5022173		6743BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FERRIS INDUSTRIES, INC. - Continued</b>			
<b>CCWKAV2461</b>			
Deck Drive .....	5100014		6893BR
Pump .....	5022173		6743BR
<b>CCWKAV2552</b>			
Deck Drive .....	5022435		6933BR
Pump .....	5022173		6743BR
<b>CCWKAV2561</b>			
Deck Drive .....	5023386		6770BR
Pump .....	5022173		6743BR
<b>DDSKAV15/48</b>			
Blade Drive .....	5020873		6749BR
Eng. To Deck .....	5021723		6754BR
Trans. ....	5022173		6743BR
<b>DDSKAV15/52</b>			
Blade Drive .....	5021297		6752BR
Deck Drive; W/52" Hanging Deck .....	5022435		6933BR
Eng. To Deck .....	5021420		6753BR
Trans. ....	5022173		6743BR
<b>DDSKAV17/48</b>			
Blade Drive .....	5020873		6749BR
Eng. To Deck .....	5021723		6754BR
Trans. ....	5022173		6743BR
<b>DDSKAV17/52</b>			
Blade Drive .....	5021297		6752BR
Deck Drive; W/52" Hanging Deck .....	5022435		6933BR
Eng. To Deck .....	5021420		6753BR
Trans. ....	5022173		6743BR
<b>DDSKAV17/61</b>			
Blade Drive .....	5020824		6748BR
Deck Drive; W/61" Hanging Deck .....	5022061		6661BR
Eng. To Deck .....	5021510		6703BR
Trans. ....	5022173		6743BR
<b>DDSKAV23/52</b>			
Blade Drive .....	5021297		6752BR
Deck Drive; W/52" Hanging Deck .....	5022435		6933BR
Eng. To Deck .....	5021420		6753BR
Trans. ....	5022173		6743BR
<b>DDSKAV23/61</b>			
Blade Drive .....	5020824		6748BR
Deck Drive; W/61" Hanging Deck .....	5022061		6661BR
Eng. To Deck .....	5021510		6703BR
Trans. ....	5022173		6743BR
<b>FW25CCKAV1548</b>			
Transaxle .....	5104354		7073BR
<b>FW25CCKAV1552</b>			
Deck Drive .....	5023496		6599BR
Transaxle .....	5104354		7073BR
<b>FW25CCKAV1936; FW25CCKAV1948</b>			
Transaxle .....	5104354		7073BR
<b>FW25CCKAV1952</b>			
Deck Drive .....	5023496		6599BR
Transaxle .....	5104354		7073BR
<b>FW25KAV1536; FW25KAV1548</b>			
Transaxle .....	5104354		7073BR
<b>FW25KAV1552</b>			
Deck Drive .....	5023496		6599BR
Transaxle .....	5104354		7073BR
<b>FW25KAV1936RDCE; FW25KAV1948</b>			
Transaxle .....	5104354		7073BR
<b>FW25KAV1952</b>			
Deck Drive .....	5023496		6599BR
Transaxle .....	5104354		7073BR
<b>FW35BV2652</b>			
Deck Drive .....	5103392		6999BR
Transaxle .....	5104193		7006BR
<b>FW35BV2661</b>			
Deck Drive .....	5103872		6936BR
Transaxle .....	5104193		7006BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FERRIS INDUSTRIES, INC. - Continued</b>			
<b>FW35BVE2852</b>			
Deck Drive .....	5103392		6999BR
Transaxle .....	5104193		7006BR
<b>FW35BVE2861</b>			
Deck Drive .....	5103872		6936BR
Transaxle .....	5104193		7006BR
<b>FW35CCBV2652</b>			
Deck Drive .....	5103392		6999BR
Transaxle .....	5104193		7006BR
<b>FW35CCBV2661</b>			
Deck Drive .....	5103872		6936BR
Transaxle .....	5104193		7006BR
<b>FW35CCBVE2852</b>			
Deck Drive .....	5103392		6999BR
Transaxle .....	5104193		7006BR
<b>FW35CCBVE2861</b>			
Deck Drive .....	5103872		6936BR
Transaxle .....	5104193		7006BR
<b>FW35CCKAV2148</b>			
Deck Drive .....	5104219		6998BR
Transaxle .....	5104193		7006BR
<b>FW35CCKAV2152</b>			
Deck Drive .....	5103392		6999BR
Transaxle .....	5104193		7006BR
<b>FW35CCKAV2461</b>			
Deck Drive .....	5103872		6936BR
Transaxle .....	5104193		7006BR
<b>FW35KAV2148; FW35KAV2148RDCE</b>			
Deck Drive .....	5104219		6998BR
Transaxle .....	5104193		7006BR
<b>FW35KAV2152; FW35KAV2152RDCE</b>			
Deck Drive .....	5103392		6999BR
Transaxle .....	5104193		7006BR
<b>FW35KAV2461</b>			
Deck Drive .....	5103872		6936BR
Transaxle .....	5104193		7006BR
<b>HC32KAV13E; HC32KAV15E</b>			
Transaxle .....	5023058		6940BR
<b>HC36KAV13E; HC36KAV15E</b>			
Eng. To Deck .....	5023262		6822BR
Transaxle .....	5023058		6940BR
<b>HDBV1648</b>			
Deck Drive .....	5021650		6665BR
<b>PCW48-12K</b>			
Deck .....	1521000		6953
Eng. To Hydro. ....	1521001		6836
<b>PCW61-14K</b>			
Eng. To Hydro. ....	1521001		6836
<b>Procut 48</b>			
Deck .....	1521000		6953
Eng. To Hydro. ....	1521001		6836
<b>Procut 61</b>			
Eng. To Hydro. ....	1521001		6836
<b>FIRESTONE</b>			
<b>08-02-500-2</b>			
Drive .....	7540114	2240	6824
<b>08-03-201-7</b>			
Belt .....	7540126		6820
<b>08-03-500-8; 08-03-508-3; 08-03-512-1; 08-03-514-8</b>			
Drive .....	7540114	2240	6824
<b>08-03-600-4; 08-03-603-9</b>			
Drive .....	7540109		6843

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FIRESTONE - Continued</b>			
<b>08-03-606-3</b>			
Belt .....	7540141		6183
Drive .....	7540239	2290	6829
<b>08-03-701-9</b>			
Blade .....	7540144	3550	6955
Drive .....	7540143		6728
<b>8D274</b>			
Belt .....	7540100	2180	6818
<b>422-3-282; 422-3-292</b>			
Drive .....	7540114	2240	6824
<b>422-3-570</b>			
Blade .....	7540144	3550	6955
Drive .....	7540143		6728
<b>422-3-693</b>			
Belt .....	7540239	2290	6829
<b>422-5-280; 422-5-290</b>			
Drive .....	7540114	2240	6824
<b>422-5-500</b>			
Belt .....	7540116	2420	6842
<b>422-5-530</b>			
Belt .....	7540935	2310	6831
<b>422-5-570</b>			
Blade .....	7540144	3550	6955
Drive .....	7540143		6728
<b>FLO-MOW</b>			
<b>SAT-21SP</b>			
Belt; W/Tecumseh Eng. ....			6734
<b>FOLEY</b>			
<b>663-01 30"</b>			
Belt .....	670757	1570	
<b>FORD</b>			
<b>09GN-3667</b>			
Drive .....	213676		6885
<b>2051; 2052; 2053; 2054; 2055; 2056</b>			
Blade .....	231511		6873
Trans. ....	231362		6745
<b>C48 Series; C48SP Series</b>			
Deck .....	11792		6996
Traction .....	390601		6376
<b>G. MCNEW CO.</b>			
<b>125-290</b>			
Drive .....	7540114		6824
<b>128-270; 9800</b>			
Traction .....	7540114		6824
<b>G.A.C.</b>			
<b>9-1441</b>			
Traction .....	7540114		6824
<b>9-1442</b>			
Traction .....	7540239		6829
<b>122-280-011</b>			
Traction .....	7540114		6824
<b>122-690-011</b>			
Traction .....	7540239		6829
<b>GAMBLE SKOGMO</b>			
<b>124-364; 124-376</b>			
Traction .....	7540252		6833
<b>150-590A</b>			
Drive .....	1651020	2180	6818
<b>2080A, 2080B</b>			
Drive .....	7540239	2290	6829

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GAMBLE SKOGMO - Continued</b>			
2095A; 2095B; 2095-OC; 2095-OE			
Drive .....	7540935	2310	6831
2096-8A			
Belt .....	7540252		6833
20554A			
Belt .....	7540114	2240	6824
26510A			
Blade .....	7540195		6854
Drive .....	7540198		6451BR
52650400			
Belt .....	42035	1400	6740
<b>GENERAL LEISURE</b>			
9HW			
Belt .....	530050004		6847
A; B; C			
Belt; W/B. & S. Eng. ....	530050005		6737
Belt; W/Tecumseh Eng. ....	530050006		6736
F			
Belt; W/B. & S. Eng. ....	530050014		6738
Belt; W/Tecumseh Eng. ....	530050005		6737
OHW			
Belt .....	530050004		6847
X			
Belt; W/B. & S. Eng. ....	530050014		6738
Belt; W/Tecumseh Eng. ....	530050005		6737
<b>GILSON</b>			
60-950-1; 60-951-2; 89-1621			
Blade .....	4638		6830
Drive .....	4825	2600	6860
56014			
Belt .....	210753		6831
15264930			
Belt .....			6833
15265028			
Belt; W/33" Belt O.C. ....			6833
Belt; W/44" Belt O.C. ....			6844
15265234			
Belt .....		2240	
<b>GOODALL</b>			
20LP			
Blade .....	W00674		6832
Eng. ....	W00672	2210	6821
22BP; 22BPA; 22BPB; 22BPC; 22BPD; 22BPE; 22BPG; 22BPX; 22BPY			
Belt .....	W00688		6738
22CP; 22CPU; 22CPV			
Blade .....	W00687		6838
Drive .....	W00685		6827
22LP; 22LPA; 22LPV; 22LPX			
Eng. To Blade .....	W00663	2400	6840
Eng. To Gear Box .....	W00664	1250	6725
24BP; 24BPU; 24BPV			
Belt .....	W00688		6738
26BP			
Clutch .....	W00682	3450	6945
Eng. ....	W00683		6826
Variable Speed .....	W00684		6932
26WP			
Clutch .....	W00682	3450	6945
Eng. ....	W00685		6827
Variable Speed .....	W00686		6834
26WPS			
Drive .....	W00676	3390	6939

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GOODALL - Continued</b>			
26WPS - Continued			
Eng. ....	W00670		6935
Reverse .....	W00673		6822
30BB; 30BC; 30BD; 30BE			
Belt .....	W00630	1570	
30BPC; 30BPD; 30BPE; 30BPG			
Belt; W/37" Belt O.C. ....	W00629		6737
Belt; W/57" Belt O.C. ....	W00630	1570	
30LF			
Belt .....	W00630	1570	
30LPF			
Belt; W/37" Belt O.C. ....	W00629		6737
Belt; W/57" Belt O.C. ....	W00630	1570	
32B; 32BA; 32BB			
Belt .....	W00678		6860
32BP; 32BPA; 32BPB; 32BPY			
Belt; W/28" Belt O.C. ....	W00660		3V280
Belt; W/33" Belt O.C. ....	W00661	1330	6733
Belt; W/60" Belt O.C. ....	W00678		6860
32BX; 32C			
Belt .....	W00678		6860
32CP			
Belt; W/28" Belt O.C. ....	W00660		3V280
Belt; W/33" Belt O.C. ....	W00661	1330	6733
Belt; W/60" Belt O.C. ....	W00678		6860
32CPT			
Belt; W/25" Belt O.C. ....	W00675		6825
Belt; W/60" Belt O.C. ....	W00678		6860
32CPU			
Blade .....	W00678		6860
32CPV			
Blade .....	W00678		6860
Drive .....	W00689		6835
32CRT			
Blade .....	W00678		6860
32LC; 32LD			
Belt .....	W00678		6860
32LP; 32LPA			
Blade .....	W00666		6848
Gear Box .....	W00659	1270	6727
32LPC; 32LPD			
Belt; W/28" Belt O.C. ....	W00660		3V280
Belt; W/33" Belt O.C. ....	W00661	1330	6733
Belt; W/60" Belt O.C. ....	W00678		6860
32LPT			
Belt; W/25" Belt O.C. ....	W00675		6825
Belt; W/60" Belt O.C. ....	W00678		6860
32LPX; 32LPY			
Blade .....	W00666		6848
Gear Box .....	W00659	1270	6727
32PIX; 32PX; 32SIX			
Belt; W/28" Belt O.C. ....	W00660		3V280
Belt; W/33" Belt O.C. ....	W00661	1330	6733
Belt; W/60" Belt O.C. ....	W00678		6860
704; 704A; 706; 707			
Belt .....	W00667		6824
708			
Belt .....	W00628		6823
726			
Belt .....	W00667		6824
728			
Belt .....	W00628		6823



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAINGER, W. W.</b>			
<b>3Z467; 3Z467A; 3Z467B; 3Z467C</b>			
Belt .....	7540109		6843
<b>3Z468</b>			
Blade .....	7540109		6843
Drive .....	7540121		6831
<b>3Z468A; 3Z468B</b>			
Blade .....	7540109		6843
Drive .....	7540177		6832
<b>3Z468G</b>			
Belt; W/33" Belt O.C. ....	7540146		6833
Belt; W/44" Belt O.C. ....	7540274		6844
<b>3Z476B</b>			
Belt .....	7540109		6843
<b>3Z501</b>			
Trans. ....	7540114		6824
<b>3Z504; 3Z504A</b>			
Drive .....	7540935		6831
<b>3Z585; 3Z585A</b>			
Belt .....	7540163		6828
<b>3Z589; 3Z589A</b>			
Blade .....	7540144	3550	6955
Drive .....	7540143		6728
<b>3Z589E</b>			
Blade .....	7540267		6859
Trans. ....	7540143		6728
<b>3Z761</b>			
Trans. ....	7540114		6824
<b>3Z762</b>			
Trans. ....	7540252	2330	6833
<b>3Z876A</b>			
Belt .....	7540116	2420	6842
<b>3Z884A</b>			
Belt .....	7540252		6833
<b>GRAVELY</b>			
<b>21" Rear Bagger</b>			
Drive .....	26150		6734
<b>21" Self-Propelled</b>			
Drive .....	26147	1300	6730
<b>22" Self-Propelled</b>			
Blade .....	26123		6827
Drive .....	25659		6724
<b>40" Self-Propelled</b>			
Drive .....	9240PI		6838
<b>528; 826</b>			
Drive .....	26121		3V335
<b>Commercial 21</b>			
Drive .....	07200637		6738
<b>Pro 8</b>			
Blade .....	41200		6862
Traction .....	041599		6549BR
<b>Pro 32</b>			
Blade .....	43318		6887
Traction .....	041599		6549BR
<b>Pro 40</b>			
Mower .....	34945		6891
Traction .....	041599		6549BR
Trans. ....	34332		6835
<b>Pro 50</b>			
Blade - Left .....	34945		6891
Blade - Right .....	34944		A44
Eng. To Deck .....	34289		6710BR
Eng. To Trans. ....	041599		6549BR
Trans. ....	41545		6835

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAVELY - Continued</b>			
<b>Pro Master 50; Pro Master 60</b>			
Front Deck; Model No. 43006 .....	031369		6387
Wing - Right; Model No. 43221 .....	031912	2490	
<b>Pro Master 350</b>			
Fan & Alt. ....		7343	
<b>Pro Master 400</b>			
Fan & Alt. ....	A38		6840
<b>Pro Power</b>			
P.T.O. ....	34864		6830
Traction .....	34346		6846
Trans. ....	34332		6835
<b>Pro-24 Brush Cutter</b>			
Blade Drive .....	07200604		6957
Clutch .....	07206000		6828
Traction .....	07200538		6822
<b>Pro-24 HWSP</b>			
Blade Drive .....	07200537		7040BR
Clutch .....	07206000		6828
Traction .....	07200538		6822
<b>Pro-26 HWSP</b>			
Blade Drive .....	07200605		6958
Clutch .....	07206000		6828
Traction .....	07200538		6822
<b>Pro-Walk32GR; Pro-Walk36GR</b>			
Deck Drive .....	07200504		6866BR
Traction .....	07400037		7124BR
Trans. ....	07225500		6948BR
<b>Pro-Walk36HR PG</b>			
Blade Drive .....	07200518		6702BR
Hydro. Drive .....	D38006		6820BR
<b>Pro-Walk36HR PS</b>			
Deck Drive .....	07200518		6702BR
Hydro. Drive .....	D38006		6820BR
<b>Pro-Walk48GR</b>			
Deck Drive .....	07240700		6589BR
Traction .....	07400037		7124BR
Trans. ....	07225500		6948BR
<b>Pro-Walk48HE PG; Pro-Walk48HE PS</b>			
Deck Drive .....	07200519		6817BR
Hydro. Drive .....	D38006		6820BR
<b>Pro-Walk52HE PG; Pro-Walk52HE PS</b>			
Deck Drive .....	00181711		6946BR
Hydro. Drive .....	D38006		6820BR
<b>Pro-Walk61HE PG; Pro-Walk61HE PS</b>			
Deck Drive .....	07200614		6732BR
Hydro. Drive .....	D38006		6820BR
<b>WAW34</b>			
Blade Drive .....	07234300		6809BR
Eng. To Deck .....	07243300		6674BR
<b>GREAT DANE</b>			
<b>GLKA1536S</b>			
Deck Drive .....	D38163		6877BR
Transaxle .....	D18388		6948BR
<b>GLKA1948S</b>			
Blade .....	D38131		6855BR
Eng. To Deck .....	D18007		6614BR
Transaxle .....	D18388		6948BR
<b>GLKA1952S</b>			
Blade .....	D38163		6877BR
Eng. To Deck .....	D38162		6482BR
Hydro. Drive .....	D18388		6948BR
<b>GLKW1536S</b>			
Deck Drive .....	D38163		6877BR
Transaxle .....	D18388		6948BR
<b>GLKW1748S</b>			
Blade .....	D38131		6855BR
Eng. To Deck .....	D18007		6614BR

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GREAT DANE - Continued</b>			
<b>GLKW1748S - Continued</b>			
Transaxle .....	D18388		6948BR
<b>TCGW52-22KHE E/S</b>			
Blade .....	D38131		6855BR
<b>TCHR36-15KA</b>			
Deck Drive .....	D38163		6877BR
Transaxle .....	D18388		6948BR
<b>TCHR48-15KA; TCHR48-17KA</b>			
Blade .....	D38131		6855BR
Eng. To Deck .....	D18007		6614BR
Transaxle .....	D18388		6948BR
<b>TCHR52-17KA</b>			
Blade .....	D38163		6877BR
Eng. To Deck .....	D38162		6482BR
Hydro. Drive .....	D18388		6948BR
<b>TCLR36-14KA</b>			
Deck Drive .....	D38007		6402BR
Hydro. Drive .....	D38006		6820BR
<b>TCLR48-17KA</b>			
Blade - Right .....	D38019		6993BR
Eng. To Deck .....	D18087		6555BR
Hydro. Drive .....	D38006		6820BR
<b>HAWN ECLIPSE</b>			
<b>3277; 3278; 3280; 3281; 3282; 3283; 3284; 3290; 3291; 3292</b>			
Blade; W/24" Belt O.C. ....	308420		6824
Blade; W/26" Belt O.C. ....	308435		6826
Wheel Drive .....	1362P		6720
<b>3293; 3294; 3295; 3296</b>			
Blade; W/24" Belt O.C. ....	308420		6824
Blade; W/26" Belt O.C. ....	308435		6826
Wheel Drive .....	1362P		6720
<b>3302; 3303; 3305; 3306; 3309; 3310; 3311; 3312; 3313</b>			
Blade .....	308446		6826
Wheel Drive .....	1362P		6720
<b>3314</b>			
Belt; W/26" Belt O.C. ....	308435		6826
Belt; W/27" Belt O.C. ....	308454		6827
<b>3315</b>			
Blade .....	308446		6826
Wheel Drive .....	1362P		6720
<b>3317; 3318</b>			
Belt .....	308435		6826
<b>3319</b>			
Belt; W/26" Belt O.C. ....	308435		6826
Belt; W/27" Belt O.C. ....	308454		6827
<b>3320; 3321; 3322; 3323; 3324</b>			
Blade .....	308446		6826
Wheel Drive .....	1362P		6720
<b>3325</b>			
Belt .....	308435		6826
<b>3326</b>			
Belt; W/26" Belt O.C. ....	308435		6826
Belt; W/27" Belt O.C. ....	308454		6827
<b>3328</b>			
Belt .....	308435		6826
<b>3329</b>			
Belt; W/26" Belt O.C. ....	308435		6826
Belt; W/27" Belt O.C. ....	308454		6827
<b>3330; 3331</b>			
Blade .....	308446		6826
Wheel Drive .....	1362P		6720
<b>3333; 3334</b>			
Belt; W/26" Belt O.C. ....	308435		6826
Belt; W/27" Belt O.C. ....	308454		6827

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HAWN ECLIPSE - Continued</b>			
<b>3335; 3336</b>			
Blade .....	308446		6826
Wheel Drive .....	1362P		6720
<b>3337; 3338; 3339</b>			
Belt .....	308453		6731
<b>3341; 3342</b>			
Blade .....	308454		6827
Wheel Drive .....	1362P		6720
<b>3343</b>			
Belt .....	308453		6731
<b>3344; 3345</b>			
Blade .....	308454		6827
Wheel Drive .....	1362P		6720
<b>3349; 3350; 3351; 3357; 3358</b>			
Belt; W/29" Belt O.C. ....	308463		6729
Belt; W/31" Belt O.C. ....	308453		6731
<b>3359; 3360; 3362; 3371; 3373; 3374</b>			
Belt .....	308453		6731
<b>3375; 3387; 3389; 3390; 3395; 3396</b>			
Blade .....	308446		6826
Wheel Drive .....	1362P		6720
<b>3402; 3403; 3404; 3405; 3406; 3407; 3408; 3409; 3410; 3411</b>			
Belt .....	308441		6843
<b>3502</b>			
Belt .....	308463		6729
<b>3508; 3510; 3511; 3512; 3513; 3520; 3544; 3547</b>			
Belt .....	308512		6730
<b>3549; 3553; 3559; 3560; 3566; 3567; 3568; 3569; 3570</b>			
Blade .....	308446		6826
Wheel Drive .....	1362P		6720
<b>3572; 3573; 3574; 3575; 3579; 4500</b>			
Belt; W/30" Belt O.C. ....	308512		6730
Belt; W/34" Belt O.C. ....	308445		6834
<b>7300; 7301; 7302; 7305</b>			
Belt .....	308441		6843
<b>7415</b>			
Belt .....	308434		3V600
<b>HANNIBAL MOWER</b>			
<b>G-22SP</b>			
Belt .....		2310	6831
<b>HARDWARE WHOLESALERS, INC.</b>			
<b>121-290; 122-290</b>			
Belt .....	7540114	2240	6824
<b>122-690; 122-692</b>			
Belt .....	7540239	2290	6829
<b>125-350; 126-350</b>			
Belt .....	7540935	2310	6831
<b>127-335</b>			
Belt .....	7540163		6828
<b>127-350</b>			
Belt .....	7540935	2310	6831
<b>128-275</b>			
Belt .....	7540114	2240	6824
<b>HARRY</b>			
<b>423</b>			
Traction; W/4-5 H.P. Eng. ....	94021002		6735
<b>471DZB</b>			
Traction; W/4 H.P. Eng. ....	10X875		6390
<b>491</b>			
Traction; W/3.5-4 H.P. Eng. ....	94021001		6730





Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HOGG</b>				<b>HOMKO - Continued</b>			
<b>E-Z Roll 5</b>				<b>51051100</b>			
Blade To Spindle; W/5.5 H.P. Eng. ....			6826	Drive .....	8597		6822
Eng. To Blade; W/5.5 H.P. Eng. ....		3620	6962	<b>51051200</b>			
Spindle To Drive; W/5.5 H.P. Eng. ....		2200	6820	Drive .....			6824
<b>HOMELITE</b>				<b>51051400; 51051500</b>			
<b>526 Series; 730 Series</b>				Drive .....	8597		6822
Blade .....	66818	2370	6837	<b>51051600; 51051800</b>			
Drive .....	66455	2510	6851	Drive .....			6824
<b>Estate</b>				<b>51083000; 51083200; 51083300; 51113000;</b>			
Reel Drive .....	312104	2350	6835	<b>51113200; 51113300</b>			
<b>HR830; HR830E; HR1230E</b>				Drive .....			6820
Blade .....	JA992639		6865	<b>51210200</b>			
Traction .....	JA992638		6839	Drive .....	8597		6822
<b>JR830; JR830E; JR930E; JR1030E; JR1230</b>				<b>51210300</b>			
Blade .....	JA991488		6873	Drive .....			6824
Traction .....	JA990738		6852	<b>52223200; 52223201; 52223400; 52223600;</b>			
<b>Lawn Prince</b>				<b>52223800; 52224000; 52230500; 52230700;</b>			
Clutch .....	314804	2200	6820	<b>52233000; 52233201</b>			
Eng. ....	313775	2200	6820	Blade .....	2363	2440	
<b>Lawn Queen</b>				<b>52270300; 52270500; 52270900; 52271100</b>			
Clutch; W/19" Belt O.C. ....	304393	2190	6819	Traction .....	20582	2430	
Clutch; W/20" Belt O.C. ....	342780	2200	6820	<b>HONDA</b>			
<b>Manor</b>				<b>HR21</b>			
Clutch .....	307870	2350	6835	Drive .....	074313		6735
<b>Pacer</b>				<b>HR21-5</b>			
Eng. ....	307913	2220	6822	Drive .....	101316		6735
<b>RE5</b>				<b>HR21K1; HR21K2</b>			
Blade .....	108248		6848	Drive .....	074313		6735
Trans. ....	158573		A29	<b>HR21-S</b>			
<b>RM5; RM5E</b>				Drive .....	23161952771		6735
Blade .....	1601524		6878	<b>HR21SDA; HR21SXA; HR21SXM</b>			
Trans. ....	1607051		6870	Drive .....	M35		6735
<b>RM7E</b>				<b>HRA21</b>			
Blade .....	1604406		6444BR	Drive .....	126151		6732
Trans. ....	1607051		6870	<b>HUFFMAN</b>			
<b>RMX8E; RMX8M; RMX11E</b>				<b>0418</b>			
Blade .....	JA991488		6873	Belt .....	BE118	2230	6823
Traction .....	JA990738		6852	<b>2212; 2281</b>			
<b>Victor</b>				Belt .....	3100140	2170	6817
Clutch .....	314804	2200	6820	<b>2418</b>			
Eng. ....	313775	2200	6820	Belt .....	BE118	2230	6823
<b>HOMKO</b>				<b>2424</b>			
<b>1151000; 1151100</b>				Belt; W/39" Belt O.C. ....	9657B	2390	6839
Drive .....			6820	Belt; W/44" Belt O.C. ....	11253	2440	6844
<b>1230000</b>				<b>2429</b>			
Traction .....	20582	2430		Belt .....	7591B	1360	6736
<b>11050700; 11050800; 11050900; 11051000;</b>				<b>4212</b>			
<b>11051100; 11051200; 11051300; 11051400;</b>				Belt .....	3100140	2170	6817
<b>11150700; 11150800</b>				<b>4218; 4219</b>			
Drive .....			6820	Belt; W/34" Belt O.C. ....	5717B	1340	6734
<b>11150900; 11151200; 11151300</b>				Belt; W/36" Belt O.C. ....	7591B	1360	6736
Drive .....			6820	<b>4245; 4247; 4248</b>			
<b>12280300; 12280400</b>				Belt .....	7591B	1360	6736
Blade .....	2363	2440		<b>4281</b>			
<b>12290100</b>				Belt .....	3100140	2170	6817
Traction .....	20582	2430		<b>4408</b>			
<b>12320000; 12320100; 12320200</b>				Belt .....	7917B	1350	6735
Blade .....	2363	2440		<b>4412</b>			
<b>21050800; 21050900; 21150500; 21150600</b>				Belt; W/17" Belt O.C. ....	3100140	2170	6817
Drive .....			6820	Belt; W/22" Belt O.C. ....	9040B		6822
<b>51050300; 51050800; 51050900</b>							
Drive .....			6824				

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUFFMAN - Continued</b>			
4418 Belt .....	BE118	2230	6823
4421 Belt; W/17" Belt O.C. .... Belt; W/22" Belt O.C. ....	3100140 9040B	2170	6817 6822
4422 Belt .....	3100140	2170	6817
4424 Belt; W/39" Belt O.C. .... Belt; W/44" Belt O.C. ....	9657B 11253	2390 2440	6839 6844
4428; 4429; 4448 Belt .....	7591B	1360	6736
4481 Belt .....	3100140	2170	6817
5019 Belt .....	5717B	1340	6734
7428 Belt .....	7591B	1360	6736
7481 Belt .....	3100140	2170	6817
8408 Belt .....	7917B	1350	6735
8428; 8448 Belt .....	7591B	1360	6736
8481; 9412 Belt .....	3100140	2170	6817
9428; 9429 Belt .....	7591B	1360	6736
9481 Belt .....	3100140	2170	6817
<b>HUSQVARNA</b>			
56CS; 56DHS Drive .....	532137078		6460BR
580BBC; 580R; 580RS; 580RSE; 580RSW; 600C Blade .....	606000226		6689BR
HU550F; HU550FH Drive .....	532196853		6426BR
HU625HWT Drive .....	532185476		6743
HU675FE; HU700F Drive .....	532426609		6426BR
HU700L Drive .....	532406557		6671BR
HU725BBC Drive .....	532406557		6671BR
HU725E Drive .....	532406557		6671BR
HU775BBC Drive .....	532406557		6671BR
HU800H Drive .....	532406557		6671BR
W3212; W3213 Trans. ....	539101957		6425BR
W3612; W3614 Deck Drive .....	539101959		6676BR
Drive .....	539101956		6813BR
Trans. ....	539101957		6425BR
W4814; W4815 Drive .....	539101956		6813BR
Trans. ....	539101957		6425BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HUSQVARNA - Continued</b>			
WH3614; WH3615 Deck Drive .....	539101959		6676BR
<b>HUSTLER EXCEL</b>			
TrimStar 14.5/36; TrimStar 15/36 Deck Drive .....	601786		6709BR
Hydro. Pump .....	601838		6734BR
TrimStar 15/48 Deck Drive .....	601969		6918BR
Hydro. Pump .....	793836		6847BR
TrimStar 17/48 Deck Drive .....	601969		6918BR
Pump .....	793836		6847BR
TrimStar 18.5/54 Deck Drive .....	601788		6646BR
Hydro. Pump .....	793836		6847BR
TrimStar 19/54 Deck Drive .....	601788		6646BR
Pump .....	793836		6847BR
TrimStar 23/54 Deck Drive .....	601788		6646BR
Hydro. Pump .....	793836		6847BR
TrimStar Gear Drive 13/32 Deck Drive .....	323003		6647BR
Drive .....	363312		6809BR
Trans. ....	363212		7025BR
TrimStar Gear Drive 15/36 Deck Drive .....	363210		6573BR
Drive .....	363312		6809BR
Trans. ....	363212		7025BR
TrimStar Gear Drive 17/48 Deck Drive .....	483030		6614BR
Drive .....	363312		6809BR
Trans. ....	363212		7025BR
TrimStar Hydro 15/36 Deck .....	788737		6685BR
Eng. To Deck .....	797514		6743BR
TrimStar Hydro 17/48 Deck; 2009 & Older .....	788745		7068BR
Deck Drive; 2010 .....	601969		6918BR
Eng. To Deck; 2009 & Older .....	788729		6996BR
Pump; 2010 .....	793836		6847BR
TrimStar Hydro 19/54; TrimStar Hydro 23/54 Deck Drive .....	601788		6646BR
Pump .....	793836		6847BR
WalkBehind 15/37 Pump Drive .....	776435		6755BR
WalkBehind 15/48; WalkBehind 17/48 Deck Drive .....	776724		6778BR
Pump Drive .....	776435		6755BR
WalkBehind 17/54 Deck Drive .....	777185		6567BR
Pump Drive .....	776435		6755BR
<b>JACOBSEN</b>			
21" S.P. Belt; W/22" Belt O.C. ....	309507		6722
Belt; W/23" Belt O.C. ....	314042		6723
Belt; W/33" Belt O.C. ....	325910		6733
Belt; W/36" Belt O.C. ....	310046		6736
Belt; W/38" Belt O.C. ....	309082	1380	6738
24" S.P. Blade .....	314012		6840
Traction .....	309360		6717
88A24 Blade; Ser. No. 4801 Thru 8500 .....	325221	3640	6964
Eng. To Blade .....	325221	3640	6964



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JACOBSEN - Continued</b>			
11801; 11804 Drive .....		2200	6820
11814 Drive ..... 307913		2220	6822
11825; 11826; 12101; 12104; 12106; 12113 Drive .....		2200	6820
22114; 22121 Drive ..... 307870		2350	6835
22601; 22611; 22615 Belt ..... 312104		2350	6835
32401 Eng. To Blade ..... 325221		3640	6964
42108 Drive ..... 501294			6733
42109; 42110; 42111 Traction ..... 325910		1330	6733
42112; 42113 Drive ..... 501294			6733
42114; 42115; 42116; 42117; 42118; 42119 Traction ..... 325910		1330	6733
42120 Drive ..... 501294			6733
42121; 42122; 42123; 42124; 42125; 42126; 42127; 42128; 42129; 42130 Traction ..... 325910		1330	6733
42131; 42132; 42133; 42134; 42135; 42136; 42137; 42138; 42139; 42140 Traction ..... 325910		1330	6733
42141; 42142 Traction ..... 325910		1330	6733
42151; 42153; 42156; 42160; 42161 Drive ..... 501294			6733
42167; 42168 Blade ..... 390165			6391
42169; 42173 Drive ..... 325910			6733
42174 Drive ..... 390164			6392
42178 Drive ..... 325910			6733
42179; 42182 Drive ..... 390164			6392
42234 Blade ..... 390165			6391
<b>Commercial 21"</b> Eng. To J.S. .... 331807 J.S. To Gear Reducer; W/32" Belt O.C. ... 331808 J.S. To Gear Reducer; W/33" Belt O.C. ... 325910			6724 6732 6733
<b>Florida Special</b> Drive ..... 325910			6733
<b>Heavy Duty 21"; Lawn King 21"</b> Belt ..... 325910			6733
<b>Lawn Prince</b> Drive; W/18" Deck; W/20" Belt O.C. .... 313775 Drive; W/19" Belt O.C. .... 304393 Drive; W/20" Belt O.C. .... 342780		2200 2190 2200	6820 6819 6820
<b>Mow-Mobile 34"; Mow-Mobile 37"; Mow-Mobile 48"</b> Drive ..... 311649 Idler ..... 311650 Starter ..... 310917		3260 2350	6926 6835
<b>Pacer 18"</b> Drive; W/20" Belt O.C. .... 313775		2200	6820

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JACOBSEN - Continued</b>			
<b>Pacer 18" - Continued</b> Drive; W/22" Belt O.C. .... 307913		2220	6822
<b>Ram SP 24"</b> Blade; W/64" Belt O.C. .... 325221 Blade; W/79" Belt O.C. .... 311621 Eng. To Gear Reducer ..... 325275 Traction ..... 310391		3640 3790 2250	6964 6979 6843 6825
<b>Turbo Cut 21" S.P.</b> Belt; W/22" Belt O.C. .... 309507 Belt; W/23" Belt O.C. .... 314042 Belt; W/36" Belt O.C. .... 310046 Belt; W/38" Belt O.C. .... 309082		1380	6722 6723 6736 6738
<b>Turbo Vac 22"</b> Belt ..... 358577		2310	6831
<b>Turbo-Vent II; Value Leader</b> Drive ..... 325910			6733
<b>Velva Trim 18"; Velva Trim 19"</b> Eng. To Cross Shaft ..... 324136 Reel Drive ..... 310391 Traction ..... 314042		2250 1230	6820 6825 6723
<b>Viscount 22" S.P.</b> Belt ..... 310046			6736
<b>JARI</b>			
<b>C Monarch</b> J.S. .... Power Unit Attachment ..... H121 Sicklebar ..... Tri Pulley ..... H119		2300 3540 3350	6830 6854 6954 6935
<b>Chief</b> Belt ..... 212100		2650	6865
<b>D</b> Eng. To Sicklebar; W/B. & S. Eng.; Ser. No. 12812 & After ..... P120 Eng. To Sicklebar; W/Lauson Eng.; Ser. No. 12812 & After ..... U120 Mule Drive; Ser. No. 12812 & After ..... D121		2310 2320 2620	6831 6832 6862
<b>E Junior</b> Eng. .... E120 Power Unit Attachment; Ser. No. 61,000 & After ..... F121 Power Unit Attachment; Ser. No. 61,000 & Before ..... E121 Tri Pulley ..... E119		2280 2480 2430 2370	6828 6848 6843 6837
<b>H Champion</b> Eng.; Ser. No. 64201 Thru 64613 ..... H120 Eng.; Ser. No. 64613 & After ..... P120 Power Unit Attachment ..... H121 Tri Pulley ..... H119		2300 2310 2540 3350	6830 6831 6854 6935
<b>K Chief</b> Power Unit Attachment ..... K121		2650	6865
<b>Monarch</b> J.S. To Blade ..... 211900		3340	6934
<b>P</b> Eng. To Sicklebar ..... P120 Mule Drive ..... P121		2310 2580	6831 6858
<b>S</b> Eng. To Sicklebar ..... P120 Mule Drive ..... S121		2310 2600	6831 6860
<b>U</b> Eng. To Sicklebar; W/B. & S. Eng. .... P120 Eng. To Sicklebar; W/Lauson Eng. .... U120		2310 2320	6831 6832
<b>JOHN DEERE</b>			
<b>7G18</b> Deck Drive; Ser. No. 020000 & Before .... TCU17942 Deck Drive; Ser. No. 020001 & After ..... TCU19456 Trans. .... AM128033			6596BR 6786BR 6593BR

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>7H17</b>			
Deck Drive; Ser. No. 030000 & Before	TCU17942		6596BR
Deck Drive; Ser. No. 030001 & After	TCU19456		6786BR
<b>20SR7</b>			
Drive	1060		6819
<b>21" S.P. Mower</b>			
Drive; W/31" Belt O.C.	M44750	1310	6731
Drive; W/33" Belt O.C.	PT13490	1330	6733
<b>32" Mower</b>			
Blade To Blade	PT8669		6844
Eng. To Blade	PT12668		6954
Variable Speed	PT8697		6940
Wheel Drive	PT8675		6550BR
<b>36" Mower</b>			
Eng. To Blade; W/11 H.P. Eng.	PT12668		6954
Eng. To Blade; W/12.5 H.P. Eng.; Ser. No. 107001 & After	PT12668		6954
Variable Speed	PT8697		6940
Wheel Drive; W/11 H.P. Eng.	PT8675		6550BR
Wheel Drive; W/12.5 H.P. Eng.; Ser. No. 750000 & Before	PT8675		6550BR
<b>38" Mower</b>			
Drive; 1993 & Newer			6887
<b>48" Mower</b>			
Blade To Blade; Ser. No. 112000 & Before	PT8716		②6846
Blade To Blade; Ser. No. 112001-116000	PT15220		②6877
Blade To Blade; Ser. No. 116001 & After	M77674	②9465	②9465HD
Eng. To Blade; Ser. No. 112000 & Before	PT8675		6550BR
Eng. To Blade; Ser. No. 112001-116000	PT15219		6963
Eng. To Blade; Ser. No. 116001 & After	M77672		6952
Traction; Ser. No. 116001-595000	M77671		6944
Trans.; Ser. No. 116001 & After	M77670	9395	9395HD
Variable Speed; Ser. No. 116000 & Before	PT8697		6940
Wheel Drive; Ser. No. 116000 & Before	PT8675		②6550BR
<b>52" Mower</b>			
Blade To Blade; Ser. No. 116000 & Before	PT8676		②6850
Blade To Blade; Ser. No. 116001 & After	M77675		②6850
Eng. To Blade; Ser. No. 116000 & Before	PT8698		6946
Eng. To Blade; Ser. No. 116001 & After	M77673		6964
Traction; Ser. No. 116001-595000	M77671		6944
Trans.; Ser. No. 160001 & After	M77670	9395	9395HD
Variable Speed; Ser. No. 116000 & Before	PT8697		6940
Wheel Drive; Ser. No. 116000 & Before	PT8675		②6550BR
<b>54" Mower</b>			
Trans.	M110797		6838
<b>260 Walk Behind Mower</b>			
Drive	AMT2800		②6824
<b>G15</b>			
Primary	M122106		6871
Trans.	M122906		6422BR
Wheel Drive	M122907		②6654BR
<b>GS25; GS30; GS45; GS75</b>			
Blade Drive; W/48" Deck	M115776		6805BR
Blade Drive; W/54" Deck	M122821		6728BR
Primary; W/36" Deck	M122106		6871
Primary; W/48" Deck	M122818		A57
Trans.	M122906		6422BR
Wheel Drive	M122907		②6654BR
<b>JA62; JA65; JE75</b>			
Drive	M77167		6734
<b>JS20</b>			
Drive	GX22269		6738
<b>JS25</b>			
Drive	GX22819		6733

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>JS26; JS28</b>			
Drive	GX23501		6426BR
<b>JS30</b>			
Drive	GX22269		6738
<b>JS35</b>			
Drive	GX22819		6733
<b>JS36; JS38</b>			
Drive	GX23549		6734
<b>JS40</b>			
Drive	GX22269		6738
<b>JS45</b>			
Drive	GX22819		6733
<b>JS46; JS48</b>			
Drive	GX23549		6734
<b>JS61</b>			
Drive	GC00073		6739
<b>JS63; JS63C; JS63E</b>			
Drive	GC00081		6735
<b>JX75</b>			
Drive; Ser. No. X200000 & Before	M77167		6734
Drive; Ser. No. X200001 & After	GX21552		6738
<b>WE80; WE85</b>			
Drive	GX23722		6738
<b>WG32A</b>			
Deck Drive; Ser. No. 040000 & Before	TCU29158		6976
Deck Drive; Ser. No. 040001 & After	TCU33096		6866BR
Eng.	TCU29283		6948BR
Traction	TCU29752		7124BR
<b>WG36A</b>			
Deck Drive; Ser. No. 040000 & Before	TCA20750		6815BR
Deck Drive; Ser. No. 040001 & After	TCU33096		6866BR
Eng.	TCU29283		6948BR
Traction	TCU29752		7124BR
<b>WG48A</b>			
Blade Drive; Ser. No. 040000 & Before	TCU29748		6812BR
Deck Drive; Ser. No. 040001 & After	TCU33100		6589BR
Eng.	TCU29283		6948BR
Traction	TCU29752		7124BR
<b>WH36A</b>			
Deck Drive	TCA20591		6702BR
P.T.O.; Ser. No. 040000 & Before	TCU29186		6820BR
P.T.O.; Ser. No. 040001 & After	TCU33063		7011BR
<b>WH48A</b>			
Deck Drive	TCU29747		6905BR
P.T.O.	TCU29186		6820BR
<b>WH52A</b>			
Deck Drive	TCA20749		6946BR
P.T.O.	TCU29186		6820BR
<b>WH61A</b>			
Deck Drive	TCU36021		6732BR
P.T.O.	TCU29186		6820BR
<b>WHP36A</b>			
Deck Drive	TCA20591		6702BR
P.T.O.	TCU33063		7011BR
<b>WHP48A</b>			
Deck Drive	TCU29747		6905BR
P.T.O.	TCU29186		6820BR
<b>WHP52A</b>			
Deck Drive	TCA20749		6946BR
P.T.O.	TCU29186		6820BR
<b>WHP61A</b>			
Deck Drive	TCU36021		6732BR
P.T.O.	TCU29186		6820BR

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>KEE</b>				<b>KEE - Continued</b>			
<b>C20</b>				<b>GC220</b>			
Blade; W/3.5 H.P. Eng. ....		2420	6842	Blade; W/B. & S., I.C. 5 H.P. Eng. ....			6848
Blade; W/B. & S. 5 H.P. Eng. ....		2410	6841	<b>GC220SP</b>			
<b>C20SP</b>				Blade; W/B. & S., I.C. 5 H.P. Eng. ....	1061		6848
Blade; W/B. & S. 5 H.P. Eng. ....		2410	6841	Trans. To Shaft; W/B. & S., I.C. 5 H.P. Eng. ....		2210	6821
Eng. To Idler; W/B. & S. 5 H.P. Eng. ....		2260	6826	<b>SC24</b>			
Idler To Gear Box; W/B. & S. 5 H.P. Eng. ....		2340	6834	P.T.O. ....			6854
<b>C22</b>				Primary ....			6727
Blade; W/3.5 H.P. Eng. ....		2460	6846	<b>SGC25</b>			
Blade; W/B. & S., I.C. 5 H.P. Eng. ....			6845	Blade; W/B. & S. 7 H.P. Eng. ....			6952
Blade; W/Kawasaki 5.2 H.P. Eng. ....			6845	Blade; W/Kawasaki, Wisconsin 7.5 H.P. Eng. ....			6952
Eng. To Idler; W/B. & S., I.C. 5 H.P. Eng. ....		2260	6826	<b>SGC25SP</b>			
Idler To Gear Box; W/B. & S., I.C. 5 H.P. Eng. ....		2340	6834	Blade; W/B. & S. 7 H.P. Eng. ....			6952
<b>C22SP</b>				Blade; W/Kawasaki, Wisconsin 7.5 H.P. Eng. ....			6952
Blade; W/3.5 H.P. Eng. ....		2460	6846	Eng. To Idler; W/B. & S. 7 H.P. Eng. ....		2270	6827
Blade; W/B. & S. 5 H.P. Eng. ....		2450	6845	Eng. To Idler; W/Kawasaki, Wisconsin 7.5 H.P. Eng. ....		2210	6821
Blade; W/Clinton 4.5 H.P. Eng. ....		2450	6845	Idler To Gear Box; W/B. & S. 7 H.P. Eng. ....		2380	6838
Blade; W/Kawasaki 5.2 H.P. Eng. ....			6845	Eng. ....			
Eng. To Idler; W/3.5 H.P. Eng. ....		2260	6826	Idler To Gear Box; W/Kawasaki 7.5 H.P. Eng. ....		2320	6832
Eng. To Idler; W/B. & S. 5 H.P. Eng. ....		2260	6826	Idler To Gear Box; W/Wisconsin 7.5 H.P. Eng. ....		2360	6836
Eng. To Idler; W/Clinton 4.5 H.P. Eng. ....		2260	6826	<b>TM22</b>			
Eng. To Idler; W/Kawasaki 5.2 H.P. Eng. ....		2250	6825	P.T.O. ....			6952
Idler To Gear Box; W/3.5 H.P. Eng. ....		2340	6834	Primary ....			6724
Idler To Gear Box; W/B. & S. 5 H.P. Eng. ....		2340	6834	<b>TM26</b>			
Eng. ....		2340	6834	P.T.O. ....			6958
Idler To Gear Box; W/Clinton 4.5 H.P. Eng. ....		2340	6834	Primary ....			6728
Idler To Gear Box; W/Kawasaki 5.2 H.P. Eng. ....		2340	6834	<b>Trailmate 2359</b>			
<b>C25</b>				J.S. To Blade ....			6845
Blade; W/B. & S. 7 H.P. Eng. ....		3560	6956	<b>KEES, F.D.</b>			
<b>C25SP</b>				<b>32" Mower Deck</b>			
Blade; W/B. & S. 7 H.P. Eng. ....		3560	6956	Traction ....	363144		6472BR
Blade; W/Kohler 8 H.P. Eng. ....			6957	<b>36" Mower Deck</b>			
Eng. To Idler; W/B. & S. 7 H.P. Eng. ....		2270	6827	Blade ....	363143		6614BR
Eng. To Idler; W/Kohler 8 H.P. Eng. ....		2210	6821	Traction ....	363144		6472BR
Idler To Gear Box; W/B. & S. 7 H.P. Eng. ....				<b>48" Mower Deck</b>			
Eng. ....		2380	6838	Blade; W/52" Belt O.C. ....	483012		6952
Idler To Gear Box; W/Kohler 8 H.P. Eng. ....		2340	6834	Blade; W/94" Belt O.C. ....			6994
<b>E-Z Roll</b>				Traction ....	363144		6472BR
Belt ....			6827	<b>36110H; 321100; 481600; 601600</b>			
J.S. To Traction ....		2220	6822	Variable Speed ....	363145		6554BR
Spindle - Center To J.S. ....			6826	<b>Powermow 361100</b>			
<b>GC22</b>				Traction ....	363144		6472BR
Blade; W/B. & S., I.C. 5 H.P. Eng. ....			6845	Variable Speed ....	363145		6554BR
Blade; W/Kawasaki 5.2 H.P. Eng. ....			6845	<b>Powermow 481100</b>			
Eng. To Idler; W/B. & S., I.C. 5 H.P. Eng. ....		2260	6826	Blade ....	483012		6952
Eng. ....				Traction ....	363144		6472BR
Idler To Gear Box; W/B. & S., I.C. 5 H.P. Eng. ....		2340	6834	Trans. ....	483023		6937
<b>GC22SP</b>				Variable Speed ....	363145		6554BR
Blade; W/Kawasaki 5.2 H.P. Eng. ....			6845	<b>KINCO</b>			
Eng. To Idler; W/Kawasaki 5.2 H.P. Eng. ....		2250	6825	<b>KMG-38</b>			
Idler To Gear Box; W/Kawasaki 5.2 H.P. Eng. ....		2340	6834	Blade ....		2380	6838
<b>GC25</b>				Traction ....			AX34
Blade; W/B. & S. 7 H.P. Eng. ....			6953	<b>K-MART</b>			
<b>GC25SP</b>				<b>124-332; 125-320; 129-336</b>			
Blade; W/B. & S. 7 H.P. Eng. ....			6953	Drive ....	7540163		6828
Blade; W/Kawasaki 7.5 H.P. Eng. ....			6952	<b>LAWN BOY</b>			
Blade; W/Kohler 8 H.P. Eng. ....			6954	<b>6100; 6200; 6210</b>			
Eng. To Idler; W/B. & S. 7 H.P. Eng. ....		2270	6827	Trans. ....	602956	1290	6729
Eng. To Idler; W/Kawasaki 7.5 H.P. Eng. ....		2210	6821	<b>8125</b>			
Eng. To Idler; W/Kohler 8 H.P. Eng. ....		2210	6821	Drive ....	611803		6733
Idler To Gear Box; W/B. & S. 7 H.P. Eng. ....							
Eng. ....		2380	6838				
Idler To Gear Box; W/Kawasaki 7.5 H.P. Eng. ....		2320	6832				
H.P. Eng. ....		2360	6836				
Idler To Gear Box; W/Kohler 8 H.P. Eng. ....							

Lawn & Garden Equipment



**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>LAWN BOY - Continued</b>			
8157; 8210; 8220; 8221; 8222; 8223; 8224; 8225; 8226			
Drive .....	612652		6732
8453			
Drive .....	611803		6733
8481			
Drive .....	612652		6732
8600; 8601; 8605			
Lower Drive .....	610040	1440	
<b>LAWN CHIEF</b>			
Hi Wheel Mower – TA210HW			
Blade .....			6940
<b>LAZY BOY</b>			
200-71			
Belt .....	1230	2400	6840
B24 Hi Wheel			
Blade .....		2600	6860
Drive .....			3V500
B24-70; B24-71			
Blade .....		2620	6862
B24SPH-66; B24SPH-67			
Belt; W/50" Belt O.C. ....			3V500
Belt; W/62" Belt O.C. ....		2620	6862
B24SPH-70; B24SPH-71			
Blade .....		2620	6862
B30SPH-66; B30SPH-67			
Belt; W/50" Belt O.C. ....			3V500
B200-9; B200-60; B200-61; B200-62; B200-63; B200-64; B200C			
Belt .....	1205	2220	6822
B200H-64; B200H-65; B200H-66; B200H-67; B200H-68; B200H-69; B200H-70; B200H-71; B200H-72; B200H-73			
Belt .....	1230	2400	6840
B200H-74; B200H-75; B200H-76			
Belt .....	1230	2400	6840
B200SPH-71; B200SPH-73; B200SPH-74; B200SPH-75; B200SPH-76			
Blade .....	1242	2340	6834
B301C			
Belt .....	1205	2220	6822
B400 Hi Wheel			
Belt .....	1237	2440	6844
B400-8			
Belt .....	1205	2220	6822
B400C			
Belt .....		2240	6824
B400H-66; B400H-67; B400H-68; B400H-69; B400H-70			
Belt .....	1237	2440	6844
B400H-71; B400H-74; B400H-75; B400H-76			
Belt; W/39" Belt O.C. ....	1236	2390	6839
Belt; W/44" Belt O.C. ....	1237	2440	6844
B400SPH-73			
Blade .....	1236	2390	6839
B2014C			
Belt .....	1205	2220	6822
C7222-73			
Belt .....	1237	2440	6844
C7222SP-73			
Blade .....	1236	2390	6839

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>LAZY BOY - Continued</b>			
DLB			
Belt .....	1288	2280	6828
FR20H-73			
Belt .....	1230	2400	6840
FRS20H-73			
Blade .....	1242	2340	6834
HDH400-79; HDH400-80; HDH500			
Belt .....	1237	2440	6844
M032; M5012; M5012T			
Belt; W/B. & S. 5 H.P. Eng. ....	1258		6840
SP501-62			
Belt; W/23" Belt O.C. ....	1208	2230	6823
SP502-63; SP502-64			
Belt .....	1221	1260	6726
SPH Hi Wheel			
Belt .....	1236	2390	6839
SPH-22" Hi Wheel S.P.			
Belt; W/50" Belt O.C. ....			3V500
SPH-63; SPH-64; SPH-65; SPH-66; SPH-67; SPH-70; SPH-71; SPH-72; SPH-73; SPH-74			
Blade .....	1236	2390	6839
SPH-75; SPH-76			
Blade .....	1236	2390	6839
W3 1721-17			
Belt .....	1236	2390	6839
WD21			
Belt .....	1230	2400	6840
WD21 SP-71			
Belt .....	1236	2390	6839
<b>LESCO</b>			
32" Walk Behind			
Mower Drive; W/Kawasaki, Kohler 12.5 H.P. Eng. ....	030779		6979
Trans.; W/Kawasaki, Kohler 12.5 H.P. Eng. ....	013874		6839
36" Walk Behind			
Mower Drive; W/Kawasaki, Kohler 12.5 H.P. Eng. ....	017249		6506BR
Trans.; W/Kawasaki, Kohler 12.5 H.P. Eng. ....	013874		6839
48" Walk Behind			
Blade Drive; W/Kawasaki, Kohler 12.5 H.P. Eng. ....	050480		6864BR
Mower Drive; W/Kawasaki, Kohler 12.5 H.P. Eng. ....	021947		6614BR
Trans.; W/Kawasaki, Kohler 12.5 H.P. Eng. ....	013874		6839
52" Commercial Mower			
Blade Drive; W/Kohler 20 H.P. Eng.; W/61" Belt O.C. ....	018352		6854BR
Blade Drive; W/Kohler 20 H.P. Eng.; W/62" Belt O.C. ....	018353		6865BR
Blower; W/Kohler 20 H.P. Eng. ....	018925		6966
P.T.O.; W/Kohler 20 H.P. Eng. ....	050477		6840
<b>LOCKE</b>			
60			
Reel Drive .....	6087	2260	6826
Traction .....	6088	2290	6829
66			
Belt .....	6304	2340	6834
75			
Reel Drive .....	6087	2260	6826
Traction .....	6088	2290	6829
Maxi-II			
Belt; W/35" Belt O.C. ....	3592	1350	6735



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>LOCKE - Continued</b>			
<b>Maxi-II – Continued</b>			
Belt; W/48" Belt O.C. ....	3280	2480	6848
Belt; W/49" Belt O.C. ....		2490	6849
<b>LONG</b>			
<b>Big Pro</b>			
Spindle .....			B120
<b>MAXIM</b>			
<b>22" Push Mower</b>			
Drive; W/5 H.P. Eng. ....	272206		6841
<b>22" S.P. Mower</b>			
Drive; W/5 H.P. Eng. ....	272227		6726
<b>24" S.P. Mower</b>			
Drive; W/8 H.P. Eng. ....	272233		6855
<b>2035BV</b>			
Belt .....	320272204	2380	6838
<b>2240BH</b>			
Belt .....	320272205	2400	6840
<b>2240BSP</b>			
Blade .....	320272205	2400	6840
Drive .....		2320	6832
<b>2240BV</b>			
Belt .....		2410	6841
<b>2250BH</b>			
Belt .....	320272205	2400	6840
<b>2450BH</b>			
Belt; W/41" Belt O.C. ....		2410	6841
Belt; W/42" Belt O.C. ....		2420	6842
<b>2450BSP</b>			
Blade .....		2420	6842
Drive .....		2330	6833
<b>GL524B High Wheel S.P.</b>			
Belt; W/30" Belt O.C.; W/5 H.P. Eng. ....	272232		6730
Belt; W/55" Belt O.C.; W/5 H.P. Eng. ....	272233		6855
<b>MCLANE</b>			
<b>17 Series</b>			
Belt .....	4060	2200	6820
<b>20 Series</b>			
Belt .....	1060	2190	6819
<b>25 Series</b>			
Belt .....	4060	2200	6820
<b>KR-2R-SP-7</b>			
Belt .....	1060		6819
<b>UG-20-4G-10</b>			
Blade .....			6823
Drive .....			6819
<b>MICHAELS MACHINE</b>			
<b>F 21"</b>			
Belt .....	F656	3560	6956
<b>FH 24"; FH 24K; FH 24W; FL 26"; FS 21"</b>			
Belt; W/38" Belt O.C. ....	F238	2380	6838
Belt; W/49" Belt O.C.; W/1/2" Belt T.W. ....	F249	2490	6849
Belt; W/49" Belt O.C.; W/21/32" Belt T.W. ....		3490	6949
Belt; W/50" Belt O.C. ....	F650	3500	6950
Belt; W/56" Belt O.C. ....	F656	3560	6956
<b>G28</b>			
Belt; W/38" Belt O.C. ....	F238	2380	6838
Belt; W/41" Belt O.C. ....	F241	2410	6841
Belt; W/42" Belt O.C. ....	F242	2420	6842
Belt; W/80" Belt O.C. ....		3800	6980
Belt; W/81" Belt O.C. ....	G681	3810	6981
<b>GL28</b>			
Belt; W/24" Belt O.C. ....		2240	6824

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MICHAELS MACHINE - Continued</b>			
<b>GL28 – Continued</b>			
Belt; W/37" Belt O.C. ....		2370	6837
Belt; W/38" Belt O.C. ....		2380	6838
Belt; W/74" Belt O.C. ....			6974
<b>GL28L</b>			
Belt; W/25" Belt O.C. ....		2250	6825
Belt; W/36" Belt O.C. ....		2360	6836
Belt; W/37" Belt O.C. ....		2370	6837
<b>RL26B; RL26K</b>			
Belt; W/30" Belt O.C. ....	R230	2300	6830
Belt; W/32" Belt O.C. ....	R232	2320	6832
Belt; W/68" Belt O.C. ....	R665		6968
<b>SP2062</b>			
Belt .....		3500	6950
<b>SP2064</b>			
Belt .....		2380	6838
<b>SP20212</b>			
Belt .....		2490	6849
<b>MIDDLESWORTH</b>			
<b>26</b>			
Mower; W/5 H.P. Eng. ....	10023		6834
Traction; W/5 H.P. Eng. ....	10026		6736
<b>MIDLAND</b>			
<b>128-272</b>			
Traction .....	7540114		6824
<b>MITCHELL MFG. CO.</b>			
<b>MSSP22; PLSP22</b>			
Belt .....	B16035	1350	6735
<b>MONO</b>			
<b>DP22</b>			
Belt .....		2318	
<b>H4-22-BR</b>			
Belt .....	G450	2450	6845
<b>HW22</b>			
Belt .....		②2260	②6826
<b>HW24</b>			
Belt .....		②2290	②6829
<b>MDR-22</b>			
Drive .....	G1341	2328	
<b>MFD-22</b>			
Drive .....	G1608	1350	6735
<b>MPX-22</b>			
Drive .....	G1277	1360	6736
<b>RFD-22</b>			
Drive .....	G1608	1350	6735
<b>RPX-22</b>			
Drive .....	G1277	1360	6736
<b>RRD-22</b>			
Drive .....	G1341	2328	
<b>MONTGOMERY</b>			
<b>22" S.P.</b>			
Belt .....		2250	6825
<b>CC34</b>			
Front Mounted Reel .....		2280	6828
<b>SL34</b>			
Belt .....			6870
<b>MONTGOMERY WARD</b>			
<b>65TBK</b>			
Belt .....	11723	2230	6823

②Two Required

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
127			
Belt .....	165120	2180	6818
169A			
Drive .....	1020699	1270	6727
175			
Belt .....	165120	2180	6818
441C			
Blade; W/43" Belt O.C. ....	7540109		6843
Blade; W/55" Belt O.C. ....	7540144	3550	6955
8317			
Belt .....	484620	1280	6728
37310			
Traction .....	7540935	2310	6831
37442			
Blade .....	7540109		6843
Drive .....	7540177		6832
37550; 37552; 37575			
Belt .....	165120	2180	6818
52987100			
Traction .....	52450	1290	
FN120A			
Belt .....	19037	2210	6821
FN5636			
Belt .....	2119	2210	6821
FN8110; FN8113A; FN8114A; FN8117A; FN8118A; FN8119A			
Belt .....	19037	2210	6821
GIL1621			
Belt; W/30" Belt O.C. ....	4638		6830
Belt; W/60" Belt O.C. ....	4825	2600	6860
HM8150H			
Belt; W/21" Belt O.C. ....	L141029	2210	6821
Belt; W/33" Belt O.C. ....	L141038	2330	6833
HM8300A; HM8300B; HM8300C			
Belt .....	L21P1290	1290	6729
HM8332A; HM8333A			
Belt .....	L19P21290	1350	6735
HM8335A			
Belt .....	L21P21290	1370	6737
TBK8310A			
Belt .....	11723	2230	6823
TDZ65			
Belt .....		1293	
TDZ69A			
Belt .....	1020699	1270	6727
TDZ71A; TDZ74A; TDZ74X			
Belt .....	1008304	1370	6737
TDZ135A; TDZ135B			
Belt .....		1293	
TDZ168A; TDZ169A			
Belt .....	1020699	1270	6727
TDZ189A			
Belt .....	1008304	1370	6737
TER108A			
Belt .....	100162	2220	6822
TM-19560			
Belt .....	JA992251		6854
TMD423D; TMD423E			
Belt; W/31" Belt O.C. ....	7540121		6831
Belt; W/43" Belt O.C. ....	7540109		6843
TMO63A			
Traction .....	7540104		6832

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
TMO89-423			
Belt; W/32" Belt O.C. ....	7540104		6832
Belt; W/43" Belt O.C. ....	7540109		6843
TMO190-500			
Belt .....	JA992251		6854
TMO226A; TMO227A; TMO229A			
Belt .....		2300	6830
TMO420A			
Traction .....	7540104		6832
TMO421A; TMO422A			
Belt .....	7540105	2300	6830
TMO441; TMO441C; TMO441D; TMO441E; TMO441F; TMO441G			
Blade .....	7540144	3550	6955
Drive .....	7540143		6728
TMO441M			
Blade .....	7540267		6859
TMO443A			
Blade .....	7540144	3550	6955
Drive .....	7540143		6728
TMO37310; TMO37315; TMO37320; TMO37320A; TMO37321; TMO37321A; TMO37321C; TMO37321D; TMO37321E; TMO37322			
Traction .....	7540935		6831
TMO37322A; TMO37322B; TMO37327; TMO37327A			
Traction .....	7540935		6831
TMO37330			
Drive .....	7540219		6826
TMO37330A			
Blade .....	7540163		6828
TMO37332; TMO37333; TMO37333B			
Traction .....	7540935		6831
TMO37334A			
Drive .....	7540292		6826
TMO37335A			
Traction .....	7540935		6831
TMO37338B			
Traction .....	7540104		6832
TMO37339A; TMO37340A; TMO37341; TMO37341A			
Traction .....	7540935		6831
TMO37343; TMO37343A; TMO37343B; TMO37344; TMO37344A			
Belt .....	7540252		6833
TMO37346B			
Drive .....	7540292		6826
TMO37351A			
Traction .....	7540935		6831
TMO37353A			
Drive .....	7540292		6826
TMO37408A			
Belt .....	7540114		6824
TMO37415A; TMO37415B; TMO37415C			
Blade .....	7540163		6828
TMO37418A			
Drive .....	7540114	2240	6824
TMO37420A; TMO37420B			
Drive .....	7540219	2260	6826
TMO37424A			
Drive .....	7540114	2240	6824



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>TMO37442A</b>			
Blade .....	7540109		6843
Drive .....	7540177		6832
<b>TMO37448B; TMO37478A; TMO37478B</b>			
Traction .....	7540341		6989
<b>TMO122303A</b>			
Traction .....	7540935		6831
<b>TMY8324</b>			
Belt .....	102625	2530	6853
<b>WFH610-1; WFH640-1</b>			
Belt .....	1108466		6833
<b>WFH37134A</b>			
Drive .....	1723661		6741
<b>WHE1427A</b>			
Drive .....	308459		3V300
<b>ZGS177A; ZGS177B; ZGS177C</b>			
Drive .....	52538	2240	6824
<b>ZMY168</b>			
Belt .....		2190	6819
<b>ZYJ99A; ZYJ99B</b>			
Belt .....	165120	2180	6818
<b>ZYJ177A 20"</b>			
Belt .....	165129	2260	6826
<b>ZYJ185A; ZYJ186A; ZYJ202A; ZYJ202B; ZYJ204A; ZYJ204B; ZYJ205A</b>			
Belt .....	165120	2180	6818
<b>ZYJ233A</b>			
Blade .....	165112	1190	6719
Drive .....	2006		6828
J.S. ....	165129	2260	6826
<b>ZYJ389A 20"</b>			
Belt .....	165129	2260	6826
<b>MOTO-MOWER</b>			
<b>61-201 21"</b>			
Belt .....	5234	1310	6731
<b>61-400 18"; 61-401 21"</b>			
Belt .....	1017723	2180	6818
<b>200</b>			
Belt .....	5234	1310	6731
<b>200 22" S.P.</b>			
Belt .....	1020699	1270	6727
<b>201; 203 S.P.; 204 S.P.</b>			
Belt .....	5234	1310	6731
<b>220 20" S.P.</b>			
Belt .....	1020699	1270	6727
<b>222 S.P.; 223 S.P.; 232 S.P.</b>			
Belt .....	5234	1310	6731
<b>420; 421; 422</b>			
Belt .....	1017723	2180	6818
<b>Deluxe 21"; Riviera 18"; Riviera 21"</b>			
Belt .....	5234	1310	6731
<b>Scout 21"</b>			
Belt; Ser. No. KSB1851 & After .....	2492	2250	6825
Belt; Ser. No. KSB4401 & After .....	2492	22250	26825
<b>Scout 22"</b>			
Belt .....	2492	22250	26825
<b>Super 61-100 18"</b>			
Belt .....	1017723	2180	6818
<b>MOTT</b>			
<b>18-60</b>			
Blade .....	186	3470	6947

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MOTT - Continued</b>			
<b>18A</b>			
Blade .....	P127	2275	
Drive .....	P322	1210	6721
<b>B9</b>			
Blade .....	P49	3580	6958
Blade - High Speed Drive .....	102	2610	6861
Drive .....	P50	23320	26932
<b>B9DP; B9DS; B9SS</b>			
Blade .....	P49	3580	6958
Drive .....	P50	23320	26932
<b>B32</b>			
Blade .....	P49	3580	6958
Blade - High Speed Drive .....	102	2610	6861
Drive .....	P50	23320	26932
<b>B32DP; B32DS; B32SP; B32SS</b>			
Blade .....	P49	3580	6958
Drive .....	P50	23320	26932
<b>FHC; G60; LB</b>			
Blade .....	186	3470	6947
<b>T38</b>			
Blade .....	P638	3390	6939
<b>MOZ-ALL</b>			
<b>L22G5; L22GP8</b>			
Blade .....	L115	2410	6841
Drive; W/18" Belt O.C. ....	218	2180	6818
Drive; W/25" Belt O.C. ....	219	2250	6825
<b>M20G3; M20GP5</b>			
Blade .....	M115	2380	6838
Drive; W/18" Belt O.C. ....	218	2180	6818
Drive; W/25" Belt O.C. ....	219	2250	6825
<b>M-22; M-22GP</b>			
Belt; W/18" Belt O.C. ....		2180	6818
Belt; W/25" Belt O.C. ....		2250	6825
Belt; W/41" Belt O.C. ....			6841
<b>SB19GB</b>			
Blade .....	219	2250	6825
<b>SD-19; SD-19B</b>			
Belt .....			6825
<b>MTD GOLD</b>			
<b>12AGB2JA004; 12AVB2M7004; 12AVB26N704</b>			
Drive .....	954-04260		6734
<b>12AVD32Q704</b>			
Drive .....	95404282		6731
<b>MTD PRODUCTS, INC.</b>			
<b>3Z467; 3Z468; 3Z468A</b>			
Blade .....	7540109		6843
Trans.; W/31" Belt O.C. ....	7540121		6831
Trans.; W/32" Belt O.C. ....	7540177		6832
<b>3Z504</b>			
Belt .....	7540935	2310	6831
<b>3Z585</b>			
Belt .....	7540163		6828
<b>3Z5389</b>			
Blade .....	7540144	3550	6955
Trans. ....	7540143		6728
<b>12A-137G; 12A-138C; 12A-138L; 12A-148</b>			
Drive; 1997 .....	7540343		6731
<b>12A-233C; 12A-234A; 12A-238B; 12A-238C; 12A-238T; 12A-239A; 12A-239N</b>			
Drive; 1999-1997 .....	7540369		6426BR
<b>12A-260A; 12A-260B; 12A-262C; 12A-263A; 12A-263B; 12A-264A; 12A-264B; 12A-264C; 12A-266F; 12A-268C</b>			
Drive; 1999-1998 .....	7540466		6737

②Two Required

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>				<b>MTD PRODUCTS, INC. - Continued</b>			
12A-269B Drive; 1999-1998 .....	7540466		6737	12B-264A Drive; W/37" Belt O.C.; 2000 .....	7540466		6737
12A-373F; 12A-375G; 12A-377G; 12A-378L; 12A-378M; 12A-378N; 12A-378Q; 12A-379A Drive .....	7540271		6557BR	Drive; W/38" Belt O.C.; 2000 .....	7540483		6738
12A-379B Drive; 2000-1997 .....	7540271		6557BR	14-270 Drive .....	7540114	2240	6824
12A-379N Drive .....	7540271		6557BR	21-4617 Belt .....	7540177	2320	6832
12A-385 Drive; 2000-1999, 1997 .....	7540271		6557BR	31A-615D; 31AE6A4E; 31AE6B3H; 31AE6C0F; 31AE553F; 31AE573H; 31AE633E; 31AE640E; 31AE640F; 31AE642E Drive .....	7540346		6411BR
12A-385A; 12A-388T; 12A-389I Drive .....	7540271		6557BR	31AE643F; 31AE644E; 31AE644F; 31AE645E; 31AE653F; 31AE660F; 31AE660G; 31AE660H; 31AE662E; 31AE662G Drive .....	7540346		6411BR
12A-443F Drive .....	7540465		6736	31AE662H; 31AE663G; 31AE663H; 31AE664F; 31AE665E; 31AE740F; 31AE753F; 31AE762F; 31AE765F; 31AH553G Drive .....	7540346		6411BR
12A-445B Drive .....	7540271		6557BR	31AH763H; 31BE640F; 31BE642F Drive .....	7540346		6411BR
12A-446D; 12A-453F Drive .....	7540465		6736	87-301 Traction .....	7540242	2320	6832
12A-455B Drive .....	7540271		6557BR	110-500 Blade .....	7540116	2420	6842
12A-455G Drive .....	7540465		6736	110-530; 110-530A Belt .....	7540109		6843
12A-458B Drive .....	7540271		6557BR	111-500 Blade .....	7540116	2420	6842
12A-458C Drive .....	7540465		6736	111-530 Belt .....	7540109		6843
12A-458P Drive .....	7540271		6557BR	112-280; 112-282 Drive .....	7540114	2240	6824
12A-459A Drive .....	7540465		6736	112-500 Blade .....	7540116	2420	6842
12A-459D Drive .....	7540271		6557BR	112-530 Belt .....	7540109		6843
12A-468N; 12A-469B Drive; 1998 .....	7540465		6736	113-500 Blade .....	7540116	2420	6842
12A-475A; 12A-478N Drive; 1997 .....	7540346		6411BR	113-530A Belt .....	7540109		6843
12A-478R Drive .....	7540346		6411BR	113-550A; 114-500A Blade .....	7540116	2420	6842
12A-528N; 12A-528T Drive; 1999-1998 .....	7540369		6426BR	114-530A Belt .....	7540109		6843
Drive; 2000 .....	7540483		6738	114-533 Blade .....	7540274		6844
12A-559K Drive; 2000-1998 .....	7540465		6736	115-290 Drive .....	7540114	2240	6824
12A-565H; 12A-565I; 12A-568N Drive; 1999-1998 .....	7540465		6736	115-500 Belt .....	7540109		6843
12A-568Q Drive; 2000 .....	7540465		6736	115-500A Blade .....	7540116	2420	6842
12A-586F; 12A-588B; 12A-588N; 12A-588P; 12A-589B; 12A-589N Drive; 1999-1998 .....	7540466		6737	115-530; 115-530A Belt .....	7540109		6843
12A-827A; 12A-829D Drive; 1999, 1997 .....	7540343		6731	115-533 Blade .....	7540274		6844
12A-959C; 12A-967K; 12A-979C; 12A-979L; 12A-999C; 12A-999L Drive; 2000-1998 .....	7540460		6739	116-322; 116-362 Traction .....	7540252		6833
12AE458G Drive .....	7540271		6557BR	116-365 Traction .....	7540292		6826
12AE458K; 12AE459F; 12AE459H Drive; 1998 .....	7540465		6736				
12AE999M Drive; 2000, 1998 .....	7540460		6739				





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
116-366 Traction .....	7540252		6833
116-367 Traction .....	7540292		6826
116-374; 116-376 Traction .....	7540252		6833
116-500 Belt .....	7540109		6843
116-500A Blade .....	7540116	2420	6842
116-530A Belt .....	7540109		6843
116-560 Blade .....	7540325		6857
Traction .....	7540327		6928
117-234 Traction .....	7540114	2240	6824
117-322 Traction .....	7540163		6828
117-362 Traction .....	7540252		6833
117-365 Traction .....	7540292		6826
117-366 Traction .....	7540252		6833
117-500; 117-500A Blade .....	7540116	2420	6842
117-530; 117-530A Belt .....	7540109		6843
117-560 Blade .....	7540326		6862
Traction .....	7540327		6928
118-500; 118-500A Blade .....	7540116	2420	6842
118-530; 118-530A; 119-530; 119-530A Belt .....	7540109		6843
120-176B; 120-178B; 120-178E Drive .....	7540343		6731
120-200; 120-220 Traction .....	7540242	2320	6832
120-232R; 120-234R; 120-236R; 120-238R Drive .....	7540369		6426BR
120-250 Belt; W/28" Belt O.C. ....	7540163		6828
Belt; W/32" Belt O.C. ....	7540242	2320	6832
120-250A; 120-255A Belt .....	7540163		6828
120-270; 120-272; 120-274; 120-280A; 120-290A Drive .....	7540114	2240	6824
120-335; 120-335A; 120-336; 120-336A Belt .....	7540163		6828
120-337; 120-337A; 120-343A Traction .....	7540252		6833
120-350A; 120-351A; 120-355A; 120-450 Belt .....	7540935	2310	6831
120-462R; 120-463R; 120-464R; 120-465R; 120-466B; 120-466R; 120-467R; 120-468B; 120-468R; 120-470R Drive .....	7540346		6411BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
120-471R; 120-472R; 120-473R; 120-474R; 120-475R; 120-476B; 120-476R; 120-477R; 120-478B; 120-478R Drive .....	7540346		6411BR
120-479R Drive .....	7540346		6411BR
120-524R; 120-526R; 120-528R Drive .....	7540369		6426BR
120-550 Blade .....	7540109		6843
Trans. ....	7540121		6831
120-550A Blade .....	7540109		6843
Trans. ....	7540177		6832
120-560B Blade .....	7540326		6862
Drive .....	7540327		6728
120-570; 120-570A Blade; W/55" Belt O.C. ....	7540144	3550	6955
Blade; W/59" Belt O.C. ....	7540267		6859
Trans. ....	7540143		6728
120-848B; 120-848E; 120-848R; 121-115R; 121-118R Drive .....	7540343		6731
121-220 Traction .....	7540242	2320	6832
121-232R; 121-233R; 121-234R; 121-236E; 121-236R; 121-238R Drive .....	7540369		6426BR
121-240 Traction .....	7540242	2320	6832
121-280; 121-282; 121-290; 121-292 Traction .....	7540114	2240	6824
121-320 Traction .....	7540242	2320	6832
121-343A Belt .....	7540252		6833
121-350A; 121-450 Belt .....	7540935	2310	6831
121-460R; 121-461R; 121-462R; 121-463R; 121-464R; 121-465R; 121-466R; 121-467R; 121-469R; 121-470R Drive .....	7540346		6411BR
121-471R; 121-472R; 121-473R; 121-474R; 121-475R; 121-476E; 121-476R; 121-477R; 121-478E; 121-478R Drive .....	7540346		6411BR
121-479R Drive .....	7540346		6411BR
121-524R; 121-526R; 121-528R Drive .....	7540369		6426BR
121-550 Blade .....	7540109		6843
Trans. ....	7540121		6831
121-550A Blade .....	7540109		6843
Trans. ....	7540177		6832
121-560B Blade .....	7540326		6862
Drive .....	7540327		6728
121-570; 121-570A Blade; W/55" Belt O.C. ....	7540144	3550	6955
Blade; W/59" Belt O.C. ....	7540267		6859
Trans. ....	7540143		6728

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
121-838E; 121-838R; 121-848R; 122-115R; 122-118R Drive .....	7540343		6731
122-220 Traction .....	7540242	2320	6832
122-232R Deck .....	7540369		6426BR
122-236R; 122-238R Drive .....	7540369		6426BR
122-280; 122-282; 122-290 Traction .....	7540114	2240	6824
122-290A Drive .....	7540114	2240	6824
Traction .....	7540114	2240	6824
122-292 Traction .....	7540114	2240	6824
122-320A Traction .....	7540163		6828
122-322 Traction .....	7540242	2320	6832
122-336A Traction .....	7540163		6828
122-343 Belt .....	7540252		6833
122-343A Belt .....	7540252	2330	
122-375A Belt .....	7540252	2330	
Traction .....	7540252		6833
122-440R; 122-442R; 122-452R; 122-456R; 122-458R Drive .....	7540271		6557BR
122-474R; 122-475R; 122-476R; 122-478B; 122-478E; 122-478R; 122-479R; 122-488R Drive .....	7540346		6411BR
122-528R Drive .....	7540369		6426BR
122-550 Blade .....	7540109	6843	
Trans. ....	7540121	6831	
122-550A Blade .....	7540109	6843	
Trans. ....	7540177	6832	
122-570 Blade; W/55" Belt O.C. ....	7540144	3550	6955
Blade; W/59" Belt O.C. ....	7540267		6859
Trans. ....	7540143		6728
122-570A Blade .....	7540267	6859	
Trans. ....	7540143	6728	
122-578; 122-650 Blade .....		6859	
Trans. ....	7540143	6728	
122-690; 122-692 Belt .....	7540239	2290	6829
123-118A Drive .....	7540343		6731
123-220 Traction .....	7540242	2320	6832
123-232A Drive .....	7540369		6426BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
123-232D; 123-232H; 123-235E; 123-236A; 123-238A; 123-238C; 123-238F; 123-238H; 123-246C Deck .....	7540369		6426BR
123-280 Traction .....	7540114	2240	6824
123-285 Drive .....	7540114	2240	6824
123-290 Traction .....	7540114	2240	6824
123-294 Drive .....	7540114	2240	6824
123-295 Traction .....	7540114	2240	6824
123-336 Traction .....	7540163		6828
123-364; 123-374 Belt .....	7540252	2330	
123-440C; 123-452B; 123-456B; 123-458B Drive .....	7540271		6557BR
123-477D; 123-478A; 123-478C; 123-478F; 123-478H; 123-479A; 123-488C; 123-488F Drive .....	7540346		6411BR
123-528A Drive .....	7540369		6426BR
123-528C; 123-528F; 123-528H Deck .....	7540369		6426BR
123-550 Blade .....	7540109	6843	
Trans. ....	7540121	6831	
123-550A Blade; W/32" Belt O.C. ....	7540177		6832
Blade; W/43" Belt O.C. ....	7540109		6843
Trans. ....	7540121		6831
123-554 Belt; W/33" Belt O.C. ....	7540146		6833
Belt; W/44" Belt O.C. ....	7540222		6844
123-570; 123-574 Blade .....	7540267	6859	
Trans. ....	7540143	6728	
123-650 Belt .....	7540935	2310	6831
123-690; 123-695 Belt .....	7540239	2290	6829
123-848C; 123E848C; 124-137; 124-138; 124-138A; 124-146; 124-146D Drive .....	7540343		6731
124-147; 124-148 Trans. ....	7540343		6731
124-224 Traction .....	7540242	2320	6832
124-232 Drive .....	7540114	2240	6824
124-232A Drive .....	7540369		6426BR
124-232D Deck .....	7540369		6426BR
124-234 Drive .....	7540114	2240	6824
124-238A; 124-238F; 124-238H Deck .....	7540369		6426BR
124-280 Drive .....	7540114	2240	6824



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
124-280A Traction .....	7540114	2240	6824
124-290A; 124-294; 124-295A Drive .....	7540114	2240	6824
124-320; 124-332 Belt .....	7540163		6828
124-350A Belt .....	7540935	2310	6831
124-362; 124-364 Traction .....	7540252		6833
124-365 Belt .....	7540252		6833
124-374; 124-376 Traction .....	7540252		6833
124-382 Belt .....	7540252		6833
124-442; 124-442B; 124-446B; 124-447G Drive .....	7540271		6557BR
124-450 Belt .....	7540935	2310	6831
124-452B; 124-457H; 124-458; 124-458B Drive .....	7540271		6557BR
124-475; 124-477D; 124-478; 124-478A; 124-478C; 124-478D; 124-478F; 124-478H; 124-487; 124-487D Drive .....	7540346		6411BR
124-488; 124-488C; 124-488F Drive .....	7540346		6411BR
124-528A Drive .....	7540369		6426BR
124-528F; 124-528Q Deck .....	7540369		6426BR
124-550 Blade; W/32" Belt O.C. ....	7540177		6832
Blade; W/43" Belt O.C. ....	7540109		6843
Trans. ....	7540121		6831
124-550A Blade .....	7540109		6843
Trans. ....	7540121		6831
124-553 Belt; W/33" Belt O.C. ....	7540146	2330	6833
Belt; W/44" Belt O.C. ....	7540274	2440	6844
124-570; 124-570A Blade .....	7540144	3550	6955
Trans. ....	7540143		6728
124-573; 124-574 Blade .....	7540267		6859
Trans. ....	7540143		6728
124-690; 124-690A; 124-695; 124-695A Belt .....	7540239	2290	6829
124-828; 124-848; 124-848C; 125-138C Drive .....	7540343		6731
125-148C Drive .....	7540369		6426BR
125-202; 125-204; 125-212; 125-214 Belt .....	7540104		6832
125-233B Deck .....	7540369		6426BR
125-234 Drive .....	7540114	2240	6824
125-234A Deck .....	7540369		6426BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
125-238C Drive .....	7540369		6426BR
125-238R Deck .....	7540369		6426BR
125-280; 125-280A Drive .....	7540114	2240	6824
125-290 Traction .....	7540114	2240	6824
125-290A; 125-294; 125-295; 125-295A Drive .....	7540114	2240	6824
125-320; 125-322 Belt .....	7540163		6828
125-350 Belt .....	7540935		6831
125-350A Belt .....	7540935	2310	6831
125-364 Traction .....	7540252		6833
125-365 Traction .....	7540292		6826
125-366 Drive; W/26" Belt O.C. ....	7540292		6826
Drive; W/33" Belt O.C. ....	7540252		6833
125-374; 125-376 Traction .....	7540252		6833
125-450 Belt .....	7540935	2310	6831
125-454B; 125-455D; 125-456B; 125-458B; 125-458S Drive .....	7540271		6557BR
125-475A; 125-475C; 125-478C; 125-478Q; 125-478R; 125-487G; 125-488C; 125-488Q; 125-488R Drive .....	7540346		6411BR
125-500A Blade .....	7540109		6843
Trans. ....	7540177		6832
125-528C Drive .....	7540369		6426BR
125-528R Deck .....	7540369		6426BR
125-550 Blade .....	7540109	2430	6843
Drive .....	7540177		6832
125-553 Blade .....	7540274		6844
Drive .....	7540146		6833
125-570; 125-570A Blade .....	7540144	3550	6955
Trans. ....	7540143		6728
125-573 Blade .....	7540267		6859
Trans. ....	7540143		6728
125-574 Belt .....	7540267		6859
125-690; 125-695 Belt .....	7540239	2290	6829
125-848C Drive .....	7540343		6731
125E448G Drive .....	7540271		6557BR
126-000 Traction .....		2320	6832

# WALK BEHIND MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>				<b>MTD PRODUCTS, INC. - Continued</b>			
<b>126-138C</b>				<b>126-550A</b>			
Drive .....	7540343		6731	Blade .....	7540109		6843
<b>126-170</b>				<b>126-560</b>			
Traction .....	7540242	2320	6832	Blade .....	7540326		6862
<b>126-202; 126-204; 126-212; 126-214; 126-216</b>				Traction .....	7540327		6928
Belt .....	7540104		6832	<b>126-570A</b>			
<b>126-220; 126-221; 126-230</b>				Blade .....	7540144	3550	6955
Traction .....	7540242	2320	6832	Trans. ....	7540143		6728
<b>126-234</b>				<b>126-828T</b>			
Drive .....	7540114	2240	6824	Drive .....	7540343		6731
<b>126-234A; 126-235A</b>				<b>126E458G; 126E458S</b>			
Deck .....	7540369		6426BR	Drive .....	7540271		6557BR
<b>126-238C</b>				<b>126E478E; 126E478O</b>			
Drive .....	7540369		6426BR	Drive .....	7540346		6411BR
<b>126-238M; 126-238T</b>				<b>127-170</b>			
Deck .....	7540369		6426BR	Traction .....	7540242	2320	6832
<b>126-240</b>				<b>127-202; 127-204; 127-212; 127-214; 127-216</b>			
Belt .....	7540935	2310	6831	Belt .....	7540104		6832
<b>126-241</b>				<b>127-220; 127-222; 127-230</b>			
Traction .....	7540242	2320	6832	Traction .....	7540242	2320	6832
<b>126-270</b>				<b>127-234</b>			
Traction .....	7540114	2240	6824	Drive .....	7540114	2240	6824
<b>126-280</b>				<b>127-240; 127-241</b>			
Belt .....	7540192		6834	Traction .....	7540242	2320	6832
<b>126-280A; 126-290A; 126-295A</b>				<b>127-270</b>			
Drive .....	7540114	2240	6824	Traction .....	7540114	2240	6824
<b>126-320; 126-322</b>				<b>127-280A; 127-290; 127-290A</b>			
Traction .....	7540163		6828	Drive .....	7540114	2240	6824
<b>126-350A</b>				<b>127-322; 127-335; 127-335A</b>			
Belt .....	7540935	2310	6831	Belt .....	7540163		6828
<b>126-351</b>				<b>127-345A</b>			
Drive .....	7540935		6831	Belt .....	7540219	2260	6826
<b>126-362; 126-364</b>				<b>127-350; 127-350A</b>			
Traction .....	7540252		6833	Belt .....	7540935	2310	6831
<b>126-365</b>				<b>127-351; 127-352</b>			
Traction .....	7540292		6826	Drive .....	7540935		6831
<b>126-366</b>				<b>127-362; 127-364</b>			
Drive; W/26" Belt O.C. ....	7540292		6826	Belt .....	7540252		6833
Drive; W/33" Belt O.C. ....	7540252		6833	<b>127-365</b>			
<b>126-367</b>				Drive; W/26" Belt O.C. ....	7540219		6826
Traction .....	7540292		6826	Drive; W/83" Belt O.C. ....	7540365		6798BR
<b>126-374; 126-376</b>				<b>127-366</b>			
Traction .....	7540252		6833	Belt .....	7540252		6833
<b>126-450</b>				<b>127-450; 127-451</b>			
Belt .....	7540935	2310	6831	Belt .....	7540935	2310	6831
<b>126-450C</b>				<b>127-550</b>			
Drive .....	7540271		6557BR	Blade .....	7540109		6843
<b>126-451</b>				Traction .....	7540104		6832
Belt .....	7540935	2310	6831	<b>127-550A</b>			
<b>126-455B; 126-458B</b>				Blade .....	7540109		6843
Drive .....	7540271		6557BR	Trans. ....	7540177		6832
<b>126-478C; 126-478L; 126-478M; 126-478N;</b>				<b>127-552</b>			
<b>126-478G; 126-488L; 126-488N; 126-488Q;</b>				Blade .....	7540109		6843
<b>126-488T</b>				Traction .....	7540104		6832
Drive .....	7540346		6411BR	<b>127-560</b>			
<b>126-528N</b>				Blade .....	7540326		6862
Drive .....	7540369		6426BR	Traction .....	7540327		6928
<b>126-528T</b>				<b>127-570A</b>			
Deck .....	7540369		6426BR	Blade .....	7540144	3550	6955
<b>126-550</b>				Trans. ....	7540143		6728
Blade .....	7540109		6843	<b>128-166R</b>			
Traction .....	7540104		6832	Traction .....	7540343	1310	6731



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>				<b>MTD PRODUCTS, INC. - Continued</b>			
128-170 Traction .....	7540105		6830	128-552 Blade .....	7540109		6843
				Trans. ....	7540121		6831
128-176B Drive .....	7540346		6411BR	128-570A Blade .....	7540144	3550	6955
				Trans. ....	7540143		6728
128-176E; 128-176R; 128-177R Traction .....	7540343	1310	6731	129-170 Traction .....	7540105		6830
128-204; 128-214; 128-216; 128-220; 128-222 Traction .....	7540104	2320	6832	129-220 Traction .....	7540242	2320	6832
128-226 Drive .....	7540114	2240	6824	129-226 Drive .....	7540114	2240	6824
128-230 Traction .....	7540242	2320	6832	129-230 Traction .....	7540242	2320	6832
128-232R Traction .....	7540114	2240	6824	129-234 Drive .....	7540114	2240	6824
128-234 Drive .....	7540114	2240	6824	129-250; 129-250A; 129-255; 129-255A Belt; W/28" Belt O.C. ....	7540163		6828
128-241 Traction .....	7540242	2320	6832	Belt; W/31" Belt O.C. ....	7540935	2310	6831
128-250; 128-250A Belt .....	7540163		6828	129-270; 129-272; 129-280; 129-280A; 129-290; 129-290A Traction .....	7540114	2240	6824
128-252R Traction .....	7540114	2240	6824	129-335 Belt; W/28" Belt O.C. ....	7540163		6828
128-255; 128-255A Belt .....	7540163		6828	Belt; W/31" Belt O.C. ....	7540935	2310	6831
128-262R; 128-266R; 128-269R; 128-270; 128-272 Traction .....	7540114	2240	6824	129-335A; 129-336; 129-336A Belt .....	7540163		6828
128-280A Drive .....	7540114	2240	6824	129-350; 129-350A Belt .....	7540935	2310	6831
Traction .....	7540114	2240	6824	129-352R; 129-353R; 129-354R Drive .....	7540935		6831
128-290 Drive .....	7540114	2240	6824	129-355A Belt .....	7540163		6828
128-290A Traction .....	7540114	2240	6824	129-355R; 129-356R; 129-357R; 129-358R; 129-359R Drive .....	7540935		6831
128-335 Belt; W/28" Belt O.C. ....	7540163		6828	129-466B; 129-476B Drive .....	7540346		6411BR
Belt; W/31" Belt O.C. ....	7540935	2310	6831	129-550 Blade .....	7540109		6843
128-335A Belt; W/28" Belt O.C. ....	7540163		6828	Trans. ....	7540121		6831
Belt; W/31" Belt O.C. ....	7540935	2310	6831	129-550A Blade .....	7540109		6843
Blade .....	7540326		6862	Trans. ....	7540177		6832
Traction .....	7540327	3280	6928	129-560B Blade .....	7540326		6862
128-336A Belt; W/28" Belt O.C. ....	7540163		6828	Traction .....	7540327	3280	6928
Belt; W/31" Belt O.C. ....	7540935	2310	6831	129-570A Blade .....	7540144	3550	6955
128-350 Drive .....	7540935	2310	6831	Trans. ....	7540143		6728
128-350A; 128-450; 128-451; 128-455 Belt .....	7540935	2310	6831	129-826R; 129-836E; 129-836R; 129-837R; 129-838R Traction .....	7540343	1310	6731
128-464R; 128-465R; 128-466B; 128-466R; 128-467R; 128-468R; 128-469R; 128-470R; 128-471R; 128-472R Drive .....	7540346		6411BR	138-478R Drive .....	7540346		6411BR
128-473R; 128-474R; 128-475R; 128-476B; 128-476R; 128-477R; 128-478B; 128-478R; 128-479R Drive .....	7540346		6411BR	150-518 Drive .....	7540126		6820
128-550 Blade .....	7540109		6843	150-590A Drive .....	1651020	2180	6818
Trans. ....	7540121		6831	151-518; 152-518 Drive .....	7540126		6820
128-550A Blade .....	7540109		6843	152-590 Belt .....	1651020	2180	
Trans. ....	7540177		6832				

Lawn & Garden Equipment



WALK BEHIND MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>				<b>MTD PRODUCTS, INC. - Continued</b>			
153-518 Drive	7540126		6820	223-8407 Drive	7540114	2240	6824
153-590 Belt	1651020	2180		233-8410 Belt	7540252		6833
154-518; 154-518A Drive	7540126		6820	270-129; 270-229 Drive	7540114	2240	6824
154-590 Belt	1651020	2180		312-610E; 312-612E; 312-640F; 312-642F; 312-660G; 313-610E; 313-612E; 313-640F; 313-642F; 313-660G	7540346		6411BR
155-510 Drive	7540100	2180	6818	315-641E; 315-661E; 315E633E; 315E640F; 315E641E; 315E643F; 315E660G; 315E663G; 315E733E; 315E740F	7540346		6411BR
155-518A Drive	7540126		6820	315E748F; 315E753F; 316-641E; 316E633E; 316E640F; 316E641E; 316E643F; 316E660G; 316E661E; 316E663G	7540346		6411BR
155-520 Drive	7540100	2180	6818	316E733E; 316E740F; 316E753F; 316E760F; 317E633E; 317E640F; 317E642E; 317E643F; 317E644E; 317E660G	7540346		6411BR
155-590 Belt	1651020	2180		317E661E; 317E662G; 317E663G; 317E663H	7540346		6411BR
156-510; 156-520 Drive	7540100	2180	6818	450-129 Belt	7540935	2310	6831
156-590 Drive	1651020	2180	6818	460R; 466B; 468B; 476B; 478B; 478E; 478R; 488R	7540346		6411BR
157-510; 157-520 Drive	7540100	2180	6818	550-129 Blade	7540104		6832
157-585; 157-585A; 157-590; 157-590A; 158-585; 158-585A; 158-590	1651020	2180		Trans.	7540109		6843
159-518 Drive	7540126		6820	623-0728; 623-0745; 623-0748; 623-0835; 623-0836; 623-2110; 623-2111; 623-2146	7540114	2240	6824
159-590A Belt	1651020	2180		643-0709; 643-0725 Traction	7540242	2320	6832
183-850; 184-850 Belt	7540141		6183	643-0756 Blade	7540104		6832
194-943 Drive	7540218		6959	Trans.	7540109		6843
194-967 Drive	7540238		6892	643-0758 Blade	7540144	3550	6955
220-046; 220-129 Traction	7540242	2320	6832	Trans.	7540143		6728
222-791 Belt	7540935	2310	6831	643-0769 Traction	7540242	2320	6832
223-703 Blade	7540109		6843	643-0775 Belt	7540935	2310	6831
Trans.	7540177		6832	643-2101 Belt	7540239	2290	6829
223-2213 Blade	7540109		6843	643-2103 Belt	7540935	2310	6831
Trans.	7540121		6831	6884 Drive	7540114	2240	6824
223-3106 Belt	7540239	2290	6829	50291 Belt	7540935	2310	6831
223-3151; 223-3206; 223-3211 Drive	7540114	2240	6824	50629 Drive	7540114	2240	6824
223-3272 Belt	7540109		6843	50631 Belt	7540252		6833
223-3286 Blade	7540109		6843	50727 Belt	7540163		6828
Trans.	7540121		6831	50728 Belt	7540252		6833
223-3403 Belt	7540935	2310	6831				
223-3411 Blade	7540116	2420	6842				
223-3421 Drive	7540114	2240	6824				
223-3429 Belt	7540163		6828				



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
50729 Belt	7540935	2310	6831
50826 Belt	7540163		6828
50832 Belt	7540935	2310	6831
1160234 Traction	7540114	2240	6824
FC5 Traction	7540242	2320	6832
FC66 Belt	7540935	2310	6831
FC67 Belt	7540163		6828
FC711 Drive	7540114	2240	6824
FC713 Belt	7540163		6828
FC714 Belt	7540935	2310	6831
K9904 Belt	7540165		6834
MS6-225P Traction	7540242	2320	6832
P2808 Drive	7540114	2240	6824
P3357; P3358; P3359 Belt	7540163		6828
P3370 Belt	7540252		6833
TMO-339906 Drive	7540346		6411BR
TMO-3747102 Deck	7540369		6426BR
Z3506 Belt	7540935	2310	6831
<b>MURRAY</b>			
0-2257 Trans.	37X25		6738
5-21981; 6-21981 Drive	37X49		6500BR
7-2255; 7-2257; 7-2267 Drive	22611	1380	6738
7-21981 Drive	37X49		6500BR
8-2155 Drive	22846	1410	6741
8-2257; 8-2267 Drive	22611	1380	6738
8-21981 Drive	37X49		6500BR
9-2257; 9-2267 Drive	22611	1380	6738
9-21981; 9-21981X5; 9-21981X12; 9-21981X79; 9-21981X96; 9-29181X62; 21981 Drive	37X49		6500BR
<b>MUTUAL BUYING SYNDICATE</b>			
123-220 Traction	7540242	2320	6832

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MUTUAL BUYING SYNDICATE - Continued</b>			
123-270 Drive	7540114	2240	6824
123-280 Traction	7540114	2240	6824
<b>NEW HORIZON</b>			
<b>Band Mower 101A</b>			
Belt; W/22" Belt O.C.		2220	6822
Belt; W/34" Belt O.C.		2340	6834
<b>NOMA</b>			
<b>36" Rear Discharge - Walk Behind Mower</b>			
Blade	43066		6520BR
2104-5000; 2104-5100; 2104-5200; 2104-5201; 2104-5300; 2104-5400; 2104-5401; 2104-5402; 2104-5500; 2104-5501 Trans.	55914		6731
2104-5600; 2104-5601; 2104-5700; 2104-5800; 2104-5801; 2104-5900 Trans.	55914		6731
2104-6000 Drive; W/B. & S. 4 H.P. Eng.	55914		6731
Trans.	55914		6731
2104-6001; 2104-6100; 2104-6300; 2104-6400; 2104-6500; 2104-6600; 2104-6700; 2104-6800; 2104-6900 Trans.	55914		6731
2105-0; 2105-0300; 2105-0400; 2105-0500; 2105-0700; 2105-0800; 2105-0900 Drive			6820
2115-0; 2115-0000; 2115-1; 2115-0100; 2115-0200; 2115-0300; 2115-0401; 2115-0500; 2115-0600 Drive	20319		6820
2135-5000; 2135-5103; 2135-5200; 2135-5400 Trans.	55914		6731
2204-65; 2204-66; 2204-69; 2204-70; 2204-5000; 2204-5100; 2204-5200; 2204-5300; 2204-5400; 2204-5401 Drive	53307	1430	
2204-5404; 2204-5500; 2204-5600; 2204-5700; 2204-5800; 2204-5801; 2204-5900; 2204-6000; 2204-6100; 2204-6200 Drive	53307	1430	
2204-6300; 2204-6400; 2204-6500; 2204-6600; 2204-6700; 2204-6800; 2204-6900; 2204-7000; 2204-7100 Drive	53307	1430	
2226-0; 2226-1; 2227-0; 2227-03; 2227-0200; 2227-0300; 2227-0500 Trans.	2363	2440	
2235-7000; 2235-7200; 2235-7300; 2235-7400; 2235-7500; 2235-7600; 2235-7900; 2235-8000; 2235-8100; 2235-8101 Drive	53307	1430	
2235-8102; 2235-8200; 2235-8300; 2235-8301; 2235-8400; 2235-8500; 2235-8501; 2235-8600; 2235-8700; 2235-8800 Drive	53307	1430	
2235-8900; 2235-9000; 2235-9100; 2235-9200; 2235-9300; 2235-9500; 2235-9600; 2235-9700; 2235-9800; 2240-5000 Drive	53307	1430	

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
2240-5100; 2240-5200; 2240-5300; 2240-5400; 2240-5500; 2240-5501; 2240-5600; 2240-5800; 2240-5900; 2240-6000 Drive .....	53307	1430	
2240-6100; 2240-6800 Drive .....	53307	1430	
3199-000 Drive .....	48529	1450	
3266-0200; 3266-0300; 3266-0400 Drive .....	53307	1430	
3298-0600 Drive .....	52450	1290	
4106-0 Drive .....	20319		6820
4106-0200; 4108-0000; 4108-0100; 4108-0101; 4120-0; 4121-000; 4124-0000; 4124-0100; 4124-0101 Drive .....	385		6848
4218-000; 4228-0000; 4228-0200; 4228-0400; 4228-0600; 4228-0800; 4229-000 Drive .....	2363	2440	
5105-0; 5105-0000; 5105-0100; 5105-0200; 5105-0401; 5105-0500 Drive .....			6824
5105-0700 Drive .....			6823
5105-0800 Drive .....			6824
5105-0900 Drive .....			6823
5105-1200 Drive .....			6824
5105-1300; 5105-1400; 5105-1500 Drive .....	8597		6822
5105-1600; 5105-1800; 5105-2100; 5105-2200; 5105-3000 Drive .....			6824
5105-3100 Drive .....	8597		6822
5105-3300; 5105-3500; 5105-3600; 5105-3700; 5105-3800; 5105-4001 Drive .....			6824
5105-4100 Drive .....			6823
5105-4200 Drive .....			6824
5105-4400; 5105-5000; 5105-6000; 5105-6500; 5105-6700 Drive .....			6823
5105-7300 Drive .....			6824
5106-0100; 5107-0100; 5107-0200; 5107-0201; 5107-0400; 5108-3000; 5108-3200; 5108-3300 Drive .....			6820
5110-0000; 5110-0100 Drive .....			6824
5111-3000; 5111-3200; 5111-3300 Drive .....			6820
5115-0000; 5115-0100 Drive .....	958		6822
5120-0; 5120-0000; 5120-0100 Drive .....			6824

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
5121-0200 Drive .....	8597		6822
5121-0300; 5121-3000; 5121-5800; 5200-0 Drive .....			6824
5222-0000; 5222-3000; 5222-3200; 5222-3201; 5222-3400; 5222-3600; 5222-3800; 5222-4000; 5223-0100; 5223-0500 Drive .....	2363	2440	
5223-0700; 5223-3000; 5223-3201; 5223-3800; 5223-3900; 5223-4300; 5223-4500; 5223-4900 Drive .....	2363	2440	
5227-0; 5227-0000; 5227-0100; 5227-0300; 5227-0500; 5227-0700; 5227-0900; 5227-1100; 5227-3100; 5227-4100 Drive .....			6843
5227-4300; 5227-4500; 5227-4700; 5227-5100; 5227-5300; 5227-5500 Drive .....			6843
5230-0; 5230-0000; 5230-0100; 5231-0100; 5231-4100; 5231-5100; 5231-6100; 5231-6101 Drive .....	2363	2440	
5265-0100; 5265-0300; 5265-0400; 5265-0500; 5265-0600; 5265-0700; 5265-0800; 5265-0900; 5265-1000; 5265-1100 Drive .....	42035	1400	
5265-1200; 5265-1300; 5265-1400; 5265-1500 Drive .....	42035	1400	
5266-3500; 5266-3600; 5266-3700; 5266-3800; 5266-3900; 5266-4000; 5266-4100; 5266-4300; 5266-4400; 5266-4500 Drive .....	53307	1430	
5298-5000; 5298-5100; 5298-5300 Drive .....	48529	1450	
5298-6000; 5298-6100; 5298-6200; 5298-6400; 5298-6500; 5298-6600; 5298-6700; 5298-6800; 5298-6900; 5298-7000 Drive .....	52450	1290	
5298-7100; 5298-7200; 5298-7300 Drive .....	52450	1290	
5302-0100 Drive .....	48529	1450	
50254 Drive .....	2363	2440	
50304 Drive .....			6823
50304A; 50306-1; 50306-3; 50306-5 Drive .....	8597		6822
50309-4 Drive .....			6824
50314 Drive .....			6823
50314A; 50316; 50316-1 Drive .....	8597		6822
12860200; 12870200 Drive .....	49233		6744
A2104-500; A2104-510; A2135-500 Drive .....	55914		6731
A2204-500; A2235-030; A2235-520; A2240-500; A2240-501 Drive .....	53307	1430	
B2105-010 Drive .....	55914		6731



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
B2204-520; B2235-520; B2240-520			
Drive .....	53307	1430	
C2105-020			
Drive .....			6731
C2204-500; C2204-510; C2205-500;			
C2235-500; C2240-520			
Drive .....	53307	1430	
D2105-510; D2105-520; D2105-570			
Drive .....			6731
D2205-500; D2205-520; D2237-500;			
D2237-510; D2250-500			
Drive .....	53307	1430	
DY510SP			
Drive .....	4231		6841
NOP4248A19			
Drive .....	53307	1430	
NT510SP			
Drive .....	4231		6841
<b>OKLAHOMA TIRE &amp; SUPPLY</b>			
45-204			
Belt .....	7540100	2180	6818
47-133-01			
Drive .....	7540252		6833
117-500			
Belt .....	7540116	2420	6842
117-500A			
Blade .....	7540116	2420	6842
120-270; 120-272			
Belt .....	7540114	2240	6824
126-240			
Belt .....	7540935	2310	6831
127-240			
Belt .....	7540242	2320	6832
127-335; 127-335A			
Belt .....	7540163		6828
127-362			
Drive .....	7540252		6833
127-550A			
Blade .....	7540109		6843
127-560			
Blade .....	7540326		6862
Traction .....	7540327		6928
128-272			
Belt .....	7540114	2240	6824
128-335; 128-335A			
Belt .....	7540163		6828
150-518; 151-518			
Belt .....	7540156		6820
156-510; 157-510			
Belt .....	7540100	2180	6818
158-518			
Belt .....	7540156		6820
1005			
Belt .....	21416	3460	6946
8500			
Belt .....	20936	3620	6962
8600			
Drive .....	610040		6744
B400			
Blade .....	1237		6844

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>OKLAHOMA TIRE &amp; SUPPLY - Continued</b>			
SPH S.P.			
Blade .....	1236		6839
<b>OLYMPIA</b>			
SP24			
Belt .....			6842
<b>OUR OWN HARDWARE</b>			
120-280; 120-282			
Traction .....	7540114	2240	6824
120-343			
Trans. ....	7540252	2330	6833
120-350			
Belt .....	7540935	2310	6831
120-550			
Blade .....	7540109		6843
Drive .....	7540104		6832
Traction .....	7540121		6831
122-690; 123-693			
Belt .....	7540239	2290	6829
124-350			
Belt .....	7540935	2310	6831
124-364			
Traction .....	7540252		6833
125-212			
Drive .....	7540104		6832
125-350			
Belt .....	7540935	2310	6831
125-364			
Trans. ....	7540252	2330	6833
126-350; 128-350			
Belt .....	7540935	2310	6831
151-518; B060-333			
Drive .....	7540126		6820
B060-515			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>PARKTON</b>			
Satellite 21"			
Belt .....	PAS20	1260	6726
<b>PENNEYS</b>			
160T			
Belt .....		2170	6817
0227			
Belt .....	7540116	2420	6842
0227A			
Belt .....	7540109		6843
0231			
Belt .....	7540116	2420	6842
0302			
Belt .....			3V315
0304; 0304A			
Blade .....	7540109		6843
Drive .....	7540121		6831
0305; 0306			
Belt .....			3V315
0307			
Belt .....	7540935	2310	6831
0324			
Blade .....	7540109		6843
Drive .....	7540177		6832
0325; 0326			
Belt .....			3V315

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PENNEYS - Continued</b>			
0327; 0327A Belt .....	7540935	2310	6831
0331; 0332 Belt .....			3V315
0334; 0334A; 0334B; 0334C Belt .....	7540935	2310	6831
0340 Belt .....	22611	1380	6738
0344; 0344A Blade .....	7540109		6843
Drive .....	7540177		6832
0345A Blade .....	7540144	3550	6955
Trans. ....	7540143		6728
0349 Blade .....	7540267		6859
Trans. ....	7540143		6728
0351; 0351A Belt .....	7540114	2240	6824
0352; 0352B Drive .....	7540219	2260	6826
0357 Drive .....	1723661		6741
0358 Belt .....	7540252		6833
0360; 0360A Belt .....	7540114	2240	6824
0502; 0502A; 0503; 0503A; 0522; 0523 Belt .....	52538	2240	6824
0524; 0526 Belt .....	1060	2190	6819
0529 Belt .....	52538	2240	6824
1030 Belt .....	7540141		6183
1248; 1248A; 1248B Belt .....	7540116	2420	6842
1321 Belt .....	308463	1290	6729
1325; 1325A; 1325M; 1326; 1327; 1327A Belt .....	37274		6732
1329; 1329A; 1331; 1332 Belt .....			3V315
1340 Deck .....	7540144		6955
Drive .....	7540143		6728
1348; 1348A Blade .....	7540109		6843
Drive .....	7540121		6831
1348B Blade .....		2430	6843
Drive .....		2320	6832
1349; 1349A Belt .....			3V315
1351 Drive .....	7540163		6828
1352 Blade .....	7540109		6843
Drive .....	7540121		6831
1600 Belt .....	52590	2200	6820
1607; 1607A; 1607B Belt .....		2170	6817

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PENNEYS - Continued</b>			
1608 Belt .....	52590	2200	6820
1616A; 1616B; 1616C Belt .....		2170	6817
1617 Belt .....	52538	2240	6824
1620; 1626A Belt .....		2170	6817
1638; 1638A Drive .....	7540126		6820
1639 Belt .....	52538	2240	6824
1649; 1659 Belt .....		2190	6819
<b>PENNSYLVANIA</b>			
4018-1; 4018A-1 Belt .....	40288	2230	6823
4018-D; 4021-D Belt .....	74211	2270	6827
4024B; 4024B-1; 4024C Belt .....	40288	2230	6823
4024-D Belt .....	74211	2270	6827
4043-1; 4043C; 4244; 4244-1; 4244C Belt .....	40288	2230	6823
7225-1; 7225A-1 Belt .....	7073C	1390	6739
7225B-1; 7225B-2 Belt .....	7073B	2380	6838
7225C Belt .....	7073C	1390	6739
8225-1 Belt .....	6983	2350	6835
40183-1; 40183-21-1; 40183-21B-1; 40183-21C; 40183-213-1; 40183-213B-1; 40183-213C-1; 40221; 40221A; 40221B Belt .....	40288	2230	6823
40221C Belt .....	40288	2230	6823
82235; 82235-1; 82235A; 82235B1; 82235C Belt .....	6983	2350	6835
407221; 407221A; 407221B; 407221C; 407221D Belt .....	40288	2230	6823
<b>POLORON</b>			
22" S.P. Belt .....	108147	1410	6741
<b>POULAN PRO</b>			
PR625Y22RHP; PR625Y22RKP; PR625Y22RP; PR625Y22SHP Drive .....	146527		6460BR
<b>POWER EQUIPMENT</b>			
22DP; 22DPW; 24DP; 24DPW; 4222 Belt .....		1380	6738
S22P; S22PH; S22PHW; S24P; S24PH; S24PHW Belt .....		1310	6731
Self Propelled Belt .....	7013	1390	6739





# WALK BEHIND MOWERS

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PRO</b>			
<b>200030; 200035</b>			
Belt .....	7520026	2430	6843
<b>200332</b>			
Belt .....	7520031	2400	6840
<b>200900</b>			
Belt .....	7529058X	2450	6845
<b>203030; 203035</b>			
Belt .....	7520026	2430	6843
<b>203332</b>			
Belt; W/31" Belt O.C. ....	7523015	2310	6831
Belt; W/40" Belt O.C. ....	7520031	2400	6840
<b>240040; 240050; 240091; 240202; 240232; 240498</b>			
Belt .....	7524026	2430	6843
<b>243050; 243091; 243202; 243232; 243498; 243702</b>			
Blade .....	7524026	2430	6843
Drive .....	7523015	2310	6831
<b>K203900</b>			
Blade .....	7529058X	2450	6845
Drive .....	7523015	2310	6831
<b>K223902; P220902</b>			
Blade .....	7522001	2470	6847
Drive .....	7523015	2310	6831
<b>P240202</b>			
Belt .....	7524026	2430	6843
<b>PROFESSIONAL HARDWARE</b>			
<b>126-364</b>			
Drive .....	7540252		6833
<b>128-272</b>			
Traction .....	7540114		6824
<b>198-651</b>			
Deck; W/32" Deck .....	7540113		6948
<b>840-6; 840-7</b>			
Blade .....	7540109	2430	6843
<b>841-6; 841-7</b>			
Blade .....	7540109	2430	6843
Traction .....	7540104	2320	6832
<b>841-8</b>			
Blade .....	7540109	2430	6843
Traction .....	7540121		6831
<b>843-6; 843-7; 843-8</b>			
Belt .....	7540114	2240	6824
<b>846-8</b>			
Blade .....	7540116	2420	6842
<b>883-6; 884-6</b>			
Belt .....	7540100	2180	6818
<b>8216-0; 8216-1; 8216-2; 8216-3; 8217-0; 8217-3; 8217-4; 8217-5; 8217-6</b>			
Belt .....	7540114	2240	6824
<b>8218-7; 8218-8</b>			
Drive .....	7540163		6828
<b>8220-2; 8220-3</b>			
Trans. ....	7540239	2290	6829
<b>8221-0; 8221-1</b>			
Blade .....	7540109	2430	6843
<b>8221-2</b>			
Belt .....	7540114	2240	6824
Blade .....	7540116	2420	6842
<b>8221-3</b>			
Blade .....	7540116	2420	6842
<b>8221-9</b>			
Blade .....	7540109	2430	6843

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PROFESSIONAL HARDWARE - Continued</b>			
<b>8224-0; 8224-1; 8224-2; 8224-3; 8224-9</b>			
Blade .....	7540109	2430	6843
Traction .....	7540121		6831
<b>8225-0; 8225-1; 8225-2; 8225-3</b>			
Blade .....	7540144	3550	6955
Traction .....	7540143		6728
<b>REO</b>			
<b>418AR; 418LR; 421AR; 421R</b>			
Belt .....	MW9363	2180	6818
<b>Flying Cloud Mower</b>			
Belt .....	MW2625	2200	6820
<b>LL-217</b>			
Drive .....	7236		6822
<b>Sabre Jet; Sabre Trim</b>			
Traction .....	MW3149	2210	6821
<b>WEF18; WFE18</b>			
Belt .....	MW1151	2170	6817
<b>ROOT</b>			
<b>20NB</b>			
Belt .....	14337	2440	6844
<b>24NB</b>			
Belt .....	14008	2520	6852
<b>24NBSP</b>			
Belt .....	14009	2260	6826
<b>2020-4A</b>			
Belt .....	6222		6864
<b>ROPER</b>			
<b>AP60AR; AP62AR; AP63AR; AP4100; BP70AR; BP70BR; BP81AR; BP4100; CL77AR; M170AR</b>			
Belt .....	83691		6734
<b>M603PR</b>			
Belt .....	83691		6734
<b>M6030AR</b>			
Drive .....	75443		6734
<b>TT213R; TT728CR</b>			
Eng. To Center Mandrel; W/42" Deck .....	6941R		<b>BX100</b>
Eng. To Outer Mandrel; W/42" Deck .....	6942R		<b>6887</b>
<b>TT738CR</b>			
Eng. To Center Mandrel; W/48" Deck .....	6941R		<b>BX100</b>
Eng. To Outer Mandrel; W/48" Deck .....	6942R		<b>6887</b>
<b>TT2041RO</b>			
Spindle - Center; W/38" Deck .....	3716R		6887
<b>TT2231R</b>			
Belt; W/48" Deck .....	6943R		6892
<b>ROYAL MOWER &amp; EDGER</b>			
<b>19" Mow King</b>			
Belt .....		2430	6843
<b>21" Mow King</b>			
Belt .....		2300	6830
<b>SPC 21" S.P.</b>			
Belt; W/27" Belt O.C. ....		2270	6827
Belt; W/29" Belt O.C. ....		2290	6829
<b>RUGG</b>			
<b>1344; 2013; 2063; 2073</b>			
Belt .....	3100140	2170	6817
<b>3131</b>			
Belt .....	3100526		6723
<b>3179R; 3180R</b>			
Belt .....	SP9413	2390	6839

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>RUGG - Continued</b>			
3280R; 3281R; 3782R; 3793RS			
Belt .....	20413	2390	6839
<b>RYAN</b>			
12SB; 12SE; 12SM; 14SB; 14SE; 14SM			
Traction .....	145871		6733
726; 727; 728			
Traction .....	610040	1440	6744
851; 852; 853; 871			
Traction .....	145120	1480	6748
<b>SARLO</b>			
416S			
Blade .....	5584		BX38
416SP			
Blade .....	5584		BX38
Drive .....	5556		6826
420			
Blade .....	5584		BX38
516SP/C			
Blade; W/5 H.P. Eng. ....	5585	3560	
524S; 524SP			
Blade .....	5584		BX38
Trans. ....		2260	6826
524SPXT/C			
Blade; W/5 H.P. Eng. ....	5557		6826
800A			
Blade .....	5555		BX56
Drive .....	5562		6824
800A-C			
Deck .....			BX56
Commercial High Wheel 24"			
Drive .....			6840
Commercial High Wheel 26"			
Eng. To Spindle .....			6956
Spindle To Drive .....	5562		6824
Commerical			
Traction; W/4 H.P. Eng. ....			6828
Commerical High Wheel			
Eng. To Deck; W/5 H.P. Eng. ....	5584		BX38
V4B2; V4B3; V5B2; V5B3			
Eng. To Deck .....	5584		BX38
<b>SCAG POWER EQUIPMENT, INC.</b>			
<b>Gear Drive</b>			
Blade - Right; W/48" Deck .....	48087		6864BR
Blade - Right; W/52" Deck .....	48285		7040BR
Blade - Right; W/72" Deck .....			6968
Deck Drive; W/32", 36" Deck .....	48204		6573BR
Deck Drive; W/48" Deck .....	48089		6701BR
Deck Drive; W/52" Deck .....	48286		6703BR
Eng. To Deck; W/61" Deck .....	48207		6702BR
Trans.; W/32", 36", 48", 52", 61", 72"			
Deck .....			6840
<b>Hydro</b>			
Blade - Right; W/48" Deck .....	48087		6864BR
Blade - Right; W/52" Deck .....	48285		7040BR
Blade - Right; W/72" Deck .....			6968
Deck Drive; W/36" Deck .....	48204		6573BR
Deck Drive; W/48" Deck .....	48089		6701BR
Deck Drive; W/52" Deck .....	48286		6703BR
Eng. To Deck; W/61" Deck .....	48207		6702BR
Hydro.; W/16" Deck .....			6950
Hydro.; W/20" Deck .....	48587		6674BR
<b>SFW36-16BV</b>			
Deck Drive .....	481880		7068BR
Wheel Drive .....	483814		7019BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>			
<b>SFW48-16BV</b>			
Wheel Drive .....	483814		7019BR
<b>SW-12B</b>			
Trans. ....	48085		6562BR
<b>SW-13BV</b>			
Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW-13K</b>			
Trans. ....	48085		6562BR
<b>SW-13KH</b>			
Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW-14KA; SW-14KH</b>			
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW-18B</b>			
Trans. ....	48080		6839
<b>SW-18EKH; SW-18KH; SW-20EKH; SW-20KHE</b>			
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW32-12B</b>			
Eng. To Deck .....	48204		6573BR
Trans. ....	48203		6840
Wheel Drive .....	482009		6552BR
<b>SW32-13BV</b>			
Eng. To Deck .....	48278		6979
Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW32-13KA</b>			
Eng. To Deck .....	48278		6979
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW32-14FS; SW32-15KA; SW32-16FS; SW32-481FS</b>			
Deck Drive .....	48278		6979
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW36-8J; SW36-12B</b>			
Eng. To Deck .....	48278		6979
Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW36-12BS; SW36-13BV</b>			
Eng. To Deck .....	48204		6573BR
Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW36-13K</b>			
Eng. To Deck .....	48278		6979
Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW36-13KA</b>			
Eng. To Deck .....	48204		6573BR
Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW36-13KH; SW36A-13KA; SW36A-13KH</b>			
Eng. To Deck .....	48204		6573BR
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW36A-14FS</b>			
Deck Drive .....	48204		6573BR
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW36A-15KA</b>			
Eng. To Deck .....	48204		6573BR
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>			
<b>SW36A-15KH; SW36A-16FS</b>			
Blade Drive .....	48204		6573BR
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW36A-16KAI</b>			
Eng. To Deck .....	48204		6573BR
Traction .....	48202A		6440BR
<b>SW36A-481FS</b>			
Blade Drive .....	48204		6573BR
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW48-12B; SW48-13BV</b>			
Blade - Right .....	48087		6864BR
Eng. To Deck .....	48089		6701BR
Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW48-13K</b>			
Blade - Right .....	48087		6864BR
Eng. To Deck .....	48089		6701BR
Eng. To Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW48-13KA; SW48-13KH</b>			
Blade - Right .....	48087		6864BR
Eng. To Deck .....	48089		6701BR
Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW48-14KA; SW48-14KH; SW48A-15KA; SW48A-15KH; SW48A-17KA; SW48A-18HN</b>			
Blade - Right .....	48087		6864BR
Eng. To Deck .....	48089		6701BR
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW48V-14FS; SW48V-15KH; SW48V-16FS; SW48V-16KAI; SW48V-481FS</b>			
Blade Drive .....	48087		6864BR
Eng. To Deck .....	48089		6701BR
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW52-13K</b>			
Blade - Right .....	48285		7040BR
Eng. To Deck .....	48286		6703BR
Eng. To Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW52-18KH</b>			
Blade - Right .....	48286		6703BR
Eng. To Deck .....	48285		7040BR
Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SW52A-17KA; SW52A-18HN; SW52A-18KH</b>			
Blade - Right .....	48285		7040BR
Eng. To Deck .....	48286		6703BR
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW52V-15FS; SW52V-17KAI; SW52V-18FS; SW52V-541FS</b>			
Blade Drive .....	48285		7040BR
Eng. To Deck .....	483518		6703BR
Trans. ....	48203		6840
Wheel Drive .....	48202A		6440BR
<b>SW61-18KH</b>			
Eng. To Deck .....	48264		B98
Eng. To Trans. ....	48203		6840
Wheel Drive .....	48202		6440BR
<b>SWZ-14KA; SWZ-14KH</b>			
Pump .....	48472		6844
<b>SWZ-17KA</b>			
Pump; W/Large Frame .....	48587		6674BR
Pump; W/Small Frame .....	48553		6553BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>			
<b>SWZ-18KH; SWZ-20KHE</b>			
Pump; W/Large Frame .....	48587		6674BR
Pump; W/Small Frame .....	48472		6844
<b>SWZ-21KAE</b>			
Pump .....	48587		6674BR
<b>SWZ36-14KA; SWZ36-14KH</b>			
Eng. To Deck .....	48204		6573BR
Pump .....	48472		6844
<b>SWZ36A-14FS</b>			
Deck Drive .....	48204		6573BR
Pump Drive .....	48553		6553BR
<b>SWZ36A-15KA</b>			
Eng. To Deck .....	48204		6573BR
Pump .....	48553		6553BR
<b>SWZ36A-16FS; SWZ36A-16KAI; SWZ36A-481FS</b>			
Deck Drive .....	48204		6573BR
Pump .....	48553		6553BR
<b>SWZ48-14KA; SWZ48-14KH</b>			
Blade - Right .....	48087		6864BR
Eng. To Deck .....	48089		6701BR
Pump .....	48472		6844
<b>SWZ48-17KA</b>			
Blade - Right .....	48087		6864BR
Eng. To Deck .....	48089		6701BR
Pump .....	48587		6674BR
<b>SWZ48A-17KA</b>			
Blade - Right .....	48087		6864BR
Eng. To Deck .....	48089		6701BR
Pump; W/Large Frame .....	48587		6674BR
Pump; W/Small Frame .....	48553		6553BR
<b>SWZ48A-17KAE</b>			
Blade - Right .....	48087		6864BR
Eng. To Deck .....	48089		6701BR
Pump .....	48553		6553BR
<b>SWZ48A-18HN</b>			
Blade - Right .....	48087		6864BR
Eng. To Deck .....	48089		6701BR
Pump .....	48553		6553BR
<b>SWZ48V-15FS; SWZ48V-17KAI; SWZ48V-18FS; SWZ48V-541FS</b>			
Blade Drive .....	48087		6864BR
Eng. To Deck .....	48089		6701BR
Pump .....	48553		6553BR
<b>SWZ52A-17KA</b>			
Blade - Right .....	48285		7040BR
Eng. To Deck .....	48286		6703BR
Pump; W/Large Frame .....	48587		6674BR
Pump; W/Small Frame .....	48553		6553BR
<b>SWZ52A-18HN; SWZ52A-18KH</b>			
Blade - Right .....	48285		7040BR
Eng. To Deck .....	48286		6703BR
Pump .....	48553		6553BR
<b>SWZ52V-17KAI</b>			
Blade Drive .....	48285		7040BR
Eng. To Deck .....	483518		6703BR
Pump .....	48553		6553BR
<b>SWZ52V-18FS</b>			
Blade Drive .....	48285		7040BR
Eng. To Deck .....	483518		6703BR
Pump; W/Large Frame .....	48587		6674BR
Pump; W/Small Frame .....	48553		6553BR
<b>SWZ52V-18KH</b>			
Blade Drive .....	48285		7040BR
Eng. To Deck .....	483518		6703BR
Pump .....	48553		6553BR

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>				<b>SEARS ROEBUCK</b>			
<b>SWZ52V-19KAI; SWZ52V-20FS</b>				<b>131.91430; 131.91441; 131.97750; 131.97751</b>			
Blade Drive .....	48285		7040BR	Belt .....	54622	2250	6825
Eng. To Deck .....	483518		6703BR	<b>131.881400; 131.881441</b>			
Pump; W/Large Frame .....	48587		6674BR	Blade .....	76019	2550	6855
Pump; W/Small Frame .....	48553		6553BR	Trans. ....	76018		6841
<b>SWZ52V-21KAE</b>				<b>131.881700; 131.881721; 131.881722</b>			
Blade Drive .....	48285		7040BR	Blade .....	76274		6859
Eng. To Deck .....	483518		6703BR	Deck .....	76275		6875
Pump .....	48587		6674BR	Trans. ....	76018		6841
<b>SWZ52V-22FSE; SWZ52V-600FS; SWZ52V-651FSE</b>				<b>131.974100; 131.974101; 131.974102; 131.974103; 131.974104; 131.974110; 131.974120</b>			
Blade Drive .....	48285		7040BR	Drive .....	75443	1340	6734
Eng. To Deck .....	483518		6703BR	<b>131.974121; 131.974123</b>			
Pump; W/Large Frame .....	48587		6674BR	Drive .....	83663		6733
Pump; W/Small Frame .....	48553		6553BR	<b>131.974140</b>			
<b>SWZ61A-21KAE</b>				Traction .....	83691		6734
Pump .....	48587		6674BR	<b>131.974141; 131.974142</b>			
<b>SWZ61V-18FS; SWZ61V-20FS; SWZ61V-21KAE; SWZ61V-22FSE; SWZ61V-600FS; SWZ61V-651FSE</b>				Drive .....	83663		6733
Eng. To Deck .....	48088		6904BR	<b>131.974200; 131.974201; 131.974202</b>			
Pump .....	48587		6674BR	Drive .....	81229	1360	6736
<b>SWZT36-14FS</b>				<b>131.974300</b>			
Deck Drive .....	484619		6702BR	Drive .....	75443	1340	6734
Trans. ....	484578		6530BR	<b>131.974310; 131.974311</b>			
<b>SWZT48-15FS</b>				Drive .....	83663		6733
Deck Drive .....	484618		6918BR	<b>131.974400; 131.974401; 131.974402</b>			
Trans. ....	484578		6530BR	Drive .....	81229	1360	6736
<b>SWZT52-18FS; SWZT52-18FSE</b>				<b>131.974500</b>			
Trans. ....	484578		6530BR	Drive .....	75443	1340	6734
<b>SWZT61-22FSE</b>				<b>131.975700; 131.975701; 131.975710; 131.975711; 131.975720; 131.975721; 131.975722</b>			
Deck Drive .....	485511		6787BR	Drive .....	74977		6736
Trans. ....	484578		6530BR	<b>131.978200; 131.978210; 131.978212; 131.978220; 131.978221; 131.978222; 131.978223; 131.978231; 131.978300</b>			
<b>SWZU36A-15KA</b>				Drive .....	75443	1340	6734
Eng. To Deck .....	481880		7068BR	<b>131.978413; 131.978415; 131.978420; 131.978421</b>			
Pump .....	481837		7012BR	Drive .....	74977		6736
<b>SWZU48A-17KA; SWZU48A-18HN</b>				<b>131.978600; 131.978610; 131.978611; 131.978800; 131.978801; 131.978810; 131.978812</b>			
Blade - Right .....	48087		6864BR	Drive .....	75671	1380	6738
Pump .....	481837		7012BR	<b>247.88100; 247.88101; 247.88102</b>			
<b>SWZU52A-17KA; SWZU52A-18HN; SWZU52A-18KH</b>				Belt .....	7540109		6843
Blade - Right .....	48285		7040BR	<b>247.88110; 247.88111</b>			
Eng. To Deck .....	481922		6806BR	Blade .....	7540109		6843
Pump .....	481837		7012BR	Trans. ....	7540121		6831
<b>SWZU52A-21KAE</b>				<b>247.88112</b>			
Blade - Right .....	48285		7040BR	Blade .....	7540109		6843
Eng. To Deck .....	481922		6806BR	Trans. ....	7540177		6832
<b>SWZU61A-21KAE</b>				<b>247.375770</b>			
Blade - Right .....	48286		6703BR	Drive .....	7540460		6739
<b>SWZV36A-16KAI</b>				<b>247.881021</b>			
Deck Drive .....	483615		6575BR	Belt .....	7540109		6843
Pump Drive .....	483520		6907BR	<b>247.881122</b>			
<b>SWZV48V-17KAI; SWZV52V-19KAI; SWZV52V-23KAE</b>				Blade .....	7540109		6843
Pump Drive .....	483520		6907BR	Trans. ....	7540177		6832
<b>Walk Behind</b>				<b>328.375301; 328.915703</b>			
Blade; W/36" Deck .....	48204		6573BR	Belt .....	1060		6819
Blade; W/52" Deck .....	48285		7040BR	<b>536.8802</b>			
Drive .....			6853	Drive .....	2363	2440	
P.T.O. To Blade; W/52" Deck .....	48286		6703BR				
Trans. ....			6840				
<b>Walk Behind 36" Hydro</b>							
P.T.O. To Blade .....	48204		6573BR				
<b>Walk Behind 48" Hydro</b>							
Blade .....	48087		6864BR				
P.T.O. To Blade .....	48089		6701BR				



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
536.81100; 536.81101 Belt .....		2240	6824
536.81110; 536.81112; 536.81113 Belt .....		2230	6823
536.81130; 536.81131; 536.81132; 536.81136 Belt .....		2240	6824
536.81140; 536.81141; 536.81142; 536.81150; 536.81151; 536.81152; 536.81170 Belt .....		2200	6820
536.81210 Belt ..... LP548		2180	6818
536.81233 Drive ..... 265111		2230	6823
536.81241 Drive ..... 41029			6822
536.81250 Belt .....		2240	6824
536.81251 Drive ..... LP383		2240	6824
536.81260; 536.81261 Drive ..... 41029			6822
536.81263; 536.81264 Drive ..... 265111		2230	6823
536.81370; 536.81371 Drive ..... LP383		2240	6824
536.81440; 536.81441; 536.81442; 536.81443; 536.81444 Drive ..... LP2154		2200	6820
536.81470; 536.81471; 536.81472; 536.81473; 536.81474; 536.81475; 536.81476; 536.81477; 536.81478; 536.81479 Drive ..... LP383		2240	6824
536.81480 Drive ..... LP2154		2200	6820
536.81481; 536.81482 Belt ..... 5165H Starter/Gen. .... 5436H		2200	6820 6731
536.81483; 536.81484 Drive ..... LP2154		2200	6820
536.81485; 536.81486 Belt .....		2200	6820
536.81490; 536.81491; 536.81492; 536.81493; 536.81494 Drive ..... LP2154		2200	6820
536.81510; 536.81520 Belt .....		2200	6820
536.81530; 536.81531 Belt ..... LP958		2220	6822
536.81570; 536.81571 Belt .....		2200	6820
536.81580 Belt .....		2240	6824
536.81591 Belt .....		2200	6820
536.81600 Drive ..... 265111		2230	6823
536.81640 Eng. To J.S. ....		2220	6822
536.81680; 536.81681; 536.81682; 536.81683 Belt .....		2200	6820
536.81720; 536.81721; 536.81723; 536.81724 Belt .....		2240	6824

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
536.81800; 536.81802; 536.81803 Drive .....		2230	6823
536.81890; 536.81891 Belt .....		2200	6820
536.81960; 536.81961; 536.81962; 536.81963; 536.81964; 536.81970; 536.81971; 536.81972; 536.81973; 536.81974 Belt .....		2240	6824
536.81975; 536.81976; 536.81978 Belt .....		2240	6824
536.81980; 536.81981; 536.81982; 536.81983; 536.81984; 536.81985; 536.81986; 536.81987; 536.81989; 536.81990 Belt .....		2200	6820
536.81991; 536.81992; 536.81993; 536.81994; 536.81995; 536.81996; 536.81997 Belt .....		2200	6820
536.82970 Belt .....		2240	6824
536.88000; 536.88001; 536.88002; 536.88003; 536.88070; 536.88071; 536.88072; 536.88220; 536.88250 Belt .....			6824
536.88280; 536.88281; 536.88960; 536.88961 Drive ..... 2363		2440	
536.88962; 536.88963 Belt .....			6824
536.91200; 536.91210 Belt ..... 383			6824
536.91300 Eng. To J.S. ....		2220	6822
536.373730; 536.375600; 536.375700; 536.375701; 536.375702; 536.375750 Blade ..... 383			6824
536.816500 Belt .....		2200	6820
536.816702 Belt .....		2240	6824
536.816900; 536.816901; 536.816902; 536.816903; 536.816904 Belt .....		2200	6820
536.817241; 536.817242; 536.817243; 536.819641 Belt .....		2240	6824
536.885600 Deck ..... 37X117 Drive ..... 37X118			6827 6719
536.978900 Drive ..... 48530		1430	6743
536.978901; 536.978902 Drive ..... 49233			6744
536.978903 Drive ..... 48530		1430	6743
536.979000; 536.979100; 536.979200 Drive ..... 49233			6744
663.904813 Belt ..... 5006471		1380	6738
663.904814 Belt ..... 105732X			6713BR
809.81200 Belt .....			6824
823.81231; 823.81232 Drive ..... 41029			6822



**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
823.81233 Belt .....	265111	2230	6823
823.81240; 823.81241; 823.81260; 823.81261 Drive .....	41029		6822
823.81263; 823.81264 Belt .....	265111	2230	6823
823.81360; 823.81361 Drive .....	41029		6822
823.81362; 823.81600 Belt .....	265111	2230	6823
828.81230 Drive .....	41029		6822
831.881800; 831.881801 Drive .....	84287		6840
917.22217X Blade .....	106085X		6672BR
917.25366 Highwheel Blade; W/50" Deck .....	3703J		68100
Drive; W/50" Deck .....	3704J		69100
917.37230 Traction .....	83691		6734
917.253592 Blade .....	6943R		6892
917.372230 Drive .....	88519		6740
917.372260; 917.372273 Traction .....	83691		6734
917.372280; 917.372282 Traction .....	88519		6740
917.372291; 917.372320; 917.372342; 917.372351; 917.372352; 917.372380; 917.372400; 917.372430; 917.372490; 917.374501 Traction .....	83691		6734
917.374502; 917.374642; 917.374750 Traction .....	83691		6734
917.374760 Traction .....	88519		6740
917.376040; 917.376041 Drive .....	146527		6460BR
917.376410; 917.376411 Drive .....	175436		6732
917.377131 Drive .....	146527		6460BR
917.377660; 917.377661; 917.377662; 917.377663; 917.377664; 917.377680; 917.377681; 917.377682; 917.377700; 917.377710 Drive .....	182212		6735
917.377780; 917.377783; 917.377790; 917.377791; 917.377792; 917.377794; 917.377820; 917.377822 Drive .....	182212		6735
917.378030 Drive .....	146527		6460BR
917.378040 Traction .....	88519		6740
917.378050 Drive .....	83691		6734
917.378060; 917.378070 Drive .....	146527		6460BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.378120; 917.378130 Traction .....	83691		6734
917.378131 Drive .....	83691		6734
917.378140 Drive .....	88519		6740
917.378150 Traction .....	88519		6740
917.378151 Drive .....	88519		6740
917.378160 Traction .....	88519		6740
917.378170; 917.378171; 917.378200 Drive .....	83691		6734
917.378210; 917.378211 Drive .....	175436		6732
917.378232; 917.378233; 917.378241; 917.378242 Traction .....	83691		6734
917.378250; 917.378251 Drive .....	83691		6734
917.378270 Drive .....	137078		6460BR
917.378271 Drive .....	83691		6734
917.378272; 917.378290 Drive .....	137078		6460BR
917.378310; 917.378320 Drive .....	146527		6460BR
917.378360; 917.378361; 917.378380; 917.378381; 917.378410; 917.378420; 917.378421; 917.378422; 917.378430; 917.378431 Drive .....	175436		6732
917.378440; 917.378441; 917.378442; 917.378450; 917.378451; 917.378452; 917.378460; 917.378461; 917.378550 Drive .....	175436		6732
917.378570; 917.378571; 917.378590; 917.378591 Drive .....	137078		6460BR
917.378600; 917.378601 Drive .....	88519		6740
917.378602 Traction .....	88519		6740
917.378620 Drive .....	88519		6740
917.378630; 917.378631 Drive .....	83691		6734
917.378632 Drive .....	137078		6460BR
917.378633 Drive .....	83691		6734
917.378650 Drive .....	137078		6460BR
917.378651 Drive .....	83691		6734
917.378652 Drive .....	137078		6460BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.378670; 917.378671; 917.378680; 917.378690; 917.378691; 917.378692; 917.378693	Drive ..... 83691		6734
917.378694	Traction ..... 83691		6734
917.378700; 917.378711	Traction ..... 88519		6740
917.378720	Traction ..... 83691		6734
917.378721; 917.378722; 917.378723	Drive ..... 83691		6734
917.378730; 917.378740	Drive ..... 88519		6740
917.378750	Drive ..... 83691		6734
917.378751; 917.378752	Drive ..... 137078		6460BR
917.378760; 917.378761; 917.378770; 917.378771; 917.378772; 917.378780; 917.378781	Drive ..... 175436		6732
917.378790	Drive ..... 88519		6740
917.378840; 917.378850; 917.378851; 917.378852; 917.378890; 917.378891; 917.378892; 917.378900	Drive ..... 175436		6732
917.378910	Drive ..... 88519		6740
917.378950	Drive; For 1999-1990 Models ..... 137078		6460BR
917.379000; 917.379001; 917.379010; 917.379030	Traction ..... 83691		6734
917.379070; 917.379071; 917.379090; 917.379100; 917.379120	Drive ..... 146527		6460BR
917.379610; 917.379611	Drive ..... 175436		6732
917.974143; 917.974144; 917.974145; 917.974152; 917.974320; 917.974321; 917.974505	Drive ..... 83691		6734
917.3722341	Traction ..... 83691		6734
<b>SENSATION</b>			
14W5 Series	Blade ..... 153101	2400	6840
21S4 Series	Blade ..... 153204		3VX400
24S5 Series	Blade ..... 153203 Trans. .... 53201	2350	6844 6835
24SP S.P.	Belt; W/34" Belt O.C. .... Belt; W/41" Belt O.C. ....	2340 3410	6834 6941
27C	Belt ..... 2260		6826
27SP-R S.P.	Belt; W/21" Belt O.C. .... Belt; W/34" Belt O.C. ....	2210 2340	6821 6834

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SENSATION - Continued</b>			
30SP S.P.	Belt; W/37" Belt O.C. .... Belt; W/41" Belt O.C. ....	2370 3410	6837 6941
36B1AC; 47578; 56043; 56044; 56045	Blade ..... 229604 Traction ..... 230836		6848 6834
56073; 56074	Deck ..... 11792		6996
G-240	Belt ..... 2460		6846
H-220	Belt ..... 2450		6845
N-210	Belt ..... 2350		6835
N-216	Belt ..... 2360		6836
SS-260	Belt ..... 3470		6947
SS424	Blade ..... 153202 Traction ..... 153201		6949 6835
<b>SENTRY</b>			
152-518; 153-518; 154-518; 155-518	Belt ..... 7540126		6820
155-520	Belt ..... 7540100	2180	6818
220-6; 230-7; 230-8	Belt ..... 7540242	2320	6832
270-6; 272-8; 274-0; 280; 290-2; 290-3; 290-4; 290-5; 294-1	Belt ..... 7540114	2240	6824
335-0; 335-7; 335-8; 335-9	Belt ..... 7540163		6828
500	Belt ..... 7540100	2180	6818
500-5; 500-6	Belt ..... 7540109		6843
500-7; 500-8	Belt ..... 7540116	2420	6842
510; 520	Belt ..... 7540100	2180	6818
550-5; 550-6	Blade ..... 7540109 Traction ..... 7540104		6843 6832
550-8	Blade ..... 7540109 Traction ..... 7540121		6843 6831
550-63	Blade ..... 7540109 Drive ..... 7540177		6843 6832
570-63	Blade ..... 7540144 Drive ..... 7540143	3550	6955 6728
<b>SIMPLICITY</b>			
520SP	Drive; Mfr. No. 1692318 ..... 1713138	0340	
1692318	Drive ..... 1713138	0340	
<b>SNAPPER</b>			
21R00C; 21R00PC; 21RX1; 21RX1P; 21RX5; 21RX5P; 214X; 214X1; 214X1P; 214X1PR	Eng. .... 12508		6534BR

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
214X1PR-2; 214X1PS; 214X1R; 214X1R-2; 214X1S; 214X2PR; 214X2PR-2; 214X4PR; 214X4PR-2; 214X5 Eng. .... 12508			6534BR
214X5-2; 214X5P; 214X5P-2; 214X5PR; 214X5PR-2; 214X5PS; 214X5R; 214X5R-2; 214X5S; 2140Y Eng. .... 12508			6534BR
2140YP; 21350; 21350D; 21350P; 21350PD; 21350PS; 21350S; 21351; 21351D; 21351P Eng. .... 12508			6534BR
21351PD; 21351PS; 21351S; 21355; 21355D; 21355P; 21355PD; 21355PS; 21355S; 21400 Eng. .... 12508			6534BR
21400P; 21401; 21401D-2; 21401P; 21401PD; 21401PD-2; 21401PS; 21401S; 21402; 21402P Eng. .... 12508			6534BR
21404; 21404P; 21404PT-2; 21404T-2; 21405; 21405-2; 21405D-2; 21405P; 21405P-2; 21405PD Eng. .... 12508			6534BR
21405PD-2; 21405PDT; 21405PN; 21405PS; 21405PT; 21405S; 21405T; 21405T-2 Eng. .... 12508			6534BR
21500C; 21500CR; 21500PC; 21500PCR Eng. .... 12353			6380
21500TC Blade ..... 12353			6380
21531; A21509B; AP21509B Eng. .... 12508			6534BR
C21500KWV; C21501KWV Eng. .... 12353			6380
CAP21509R Eng. .... 12508			6534BR
CLP21650RV Traction ..... 6733			6733
CP21400R2; CP21402R2; CP21500KWV; CP21501KWV Eng. .... 12353			6380
CP21507R; CP21557BV Eng. .... 12353			6380
CP214012R2; CP215512KWV; CP216012RV; CP216512RV Eng. .... 12353			6380
CV21; CV212; CV212H; CV212P; CV212PH; CV21507B; CV21507R; CVP21507R; CVP21507R2; ECP21407R2 Eng. .... 12353			6380
EP21508B Eng. .... 12508			6534BR
FRP21600TV; FRP216012; FRP216012E; FRP216012TV; FRP216016; FRPS216015E Eng. .... 12353			6380
G214X5-2; G214X5P-2; G21355; G21404P; G21405; G21405P; G21405PS; G21500PC Eng. .... 12508			6534BR
GPC21507B; GPC21507BV Eng. .... 12353			6380
NFRP216012E; ODP21400; P21500 Eng. .... 12353			6380
P21508B; P21558BV Eng. .... 12508			6534BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
P21600; P21600TV Eng. .... 12353			6380
P216012; P216012E Eng.; W/24 3/4" Belt O.C. .... 12508 Eng.; W/25 1/2" Belt O.C. .... 12353			6534BR 6380
P216012TV; PB21550V Eng. .... 12353			6380
PC21507B; PC21507R Eng. .... 12353			6380
PL7140KWV Blade To Blade; W/48" Deck ..... 19205 Eng. To Deck; W/36" Deck ..... 38624 Eng. To Trans. .... 17334 Traction ..... 17333			6952 6983 6840 6470BR
PL8140KVE; PL8180KE; PL8480KE Blade To Blade; W/48" Deck ..... 19205 Eng. To Deck; W/36", 48" Deck ..... 38624 Traction ..... 17053			6952 6983 6593BR
PL71250KW Blade To Blade; W/48" Deck ..... 19205 Eng. To Deck; W/36" Deck ..... 38624 Eng. To Trans. .... 17334 Traction ..... 17333			6952 6983 6840 6470BR
PMA360 Eng. To Deck; W/36" Deck ..... 38624 Traction ..... 17053			6983 6593BR
PMA480 Blade To Blade; W/48" Deck ..... 19205 Eng. To Deck; W/48" Deck ..... 38624 Traction ..... 17053			6952 6983 6593BR
PMA510; PMA520; PMA610 Traction ..... 17053			6593BR
PMA8360 Eng. To Deck; W/36" Deck ..... 38624 Traction ..... 17053			6983 6593BR
PMA8480 Blade To Blade; W/48" Deck ..... 19205 Eng. To Deck; W/48" Deck ..... 38624 Traction ..... 17053			6952 6983 6593BR
PMA8520; PMA8610 Traction ..... 17053			6593BR
PP7140KWV; PP71250KW Blade To Blade; W/48" Deck ..... 19205 Eng. To Deck; W/36" Deck ..... 38624 Eng. To Trans. .... 17334 Traction ..... 17333			6952 6983 6840 6470BR
PPU140KO; PPU140KVE; PPU140KW; PPU140R; PPU180KE Blade To Blade; W/48" Deck ..... 19205 Eng. To Deck; W/36", 48" Deck ..... 38624 Traction ..... 17053			6952 6983 6593BR
RP20500 Drive ..... 28382			6737
RP21400; RP21500; RP21500T2; RP21501; RP21600; RP21600E; RP215012; RP215012T2; RP216012 Eng. .... 12353			6380
Series 21; Series O Traction ..... 12353			6380
SPL140KH; SPL140KW Eng. To Deck; W/36" Deck ..... 35710 Primary Drive; W/48" Deck ..... 29262 Primary Drive; W/52" Deck ..... 29267 Traction; W/Dual Belts; W/36", 48", 52" Deck ..... 28906 Traction; W/Single Belt; W/36", 48", 52" Deck ..... 17334 Trans.; Early; W/36", 48", 52" Deck .....			6702BR 6966 6968 ②A50 6852 6840

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>SPL140KH; SPL140KW – Continued</b>			
Trans.; Late; W/36", 48", 52" Deck .....	16029		6839
<b>SPL1250KW</b>			
Eng. To Deck; W/32" Deck .....	36403		6978
Eng. To Deck; W/36" Deck .....	35710		6702BR
Eng. To Deck; W/48" Deck .....	29262		6966
Eng. To Deck; W/52" Deck .....	29267		6968
Traction; W/Dual Belts; W/36" Deck .....	28906		②A50
Traction; W/Single Belt .....			6852
Trans.; Early; W/36" Deck .....	17334		6840
Trans.; Late .....	16029		6839
<b>SPLH140KH; SPLH140KW</b>			
Eng. To Deck; W/36" Deck .....	35710		6702BR
Primary Drive; W/48" Deck .....	29262		6966
Primary Drive; W/52" Deck .....	29267		6968
Traction; W/Dual Belts; W/36", 48", 52" Deck .....	28906		②A50
Traction; W/Single Belt; W/36", 48", 52" Deck .....			6852
Trans.; Early; W/36", 48", 52" Deck .....	17334		6840
Trans.; Late; W/36", 48", 52" Deck .....	16029		6839
<b>SPLH160BV</b>			
Deck Drive; W/36" Deck .....	35710		6702BR
Eng. To Deck; W/36" Deck .....	29255		6985
Eng. To Deck; W/52" Deck .....	29267		6968
Primary Drive; W/48" Deck .....	29262		6966
Primary Drive; W/52" Deck .....	29267		6968
<b>SPLH180KHE</b>			
Eng. To Deck; W/52" Deck .....	29267		6968
Eng. To Deck; W/61" Deck .....	29269		6974
Primary Drive; W/48" Deck .....	29262		6966
Primary Drive; W/52" Adj. Deck .....	42813		6482BR
Primary Drive; W/52" Fixed Deck .....	29267		6968
Primary Drive; W/61" Adj. Deck .....	42735		6402BR
<b>SPP90KW</b>			
Eng. To Deck .....	36403		6978
Trans.; Early .....	17334		6840
Trans.; Late .....	16029		6839
<b>SPP140KH</b>			
Eng. To Deck; W/36" Deck .....	35710		6702BR
Primary Drive; W/48" Deck .....	29262		6966
Primary Drive; W/52" Deck .....	29267		6968
Traction; W/Dual Belts; W/36", 48", 52" Deck .....	28906		②A50
Traction; W/Single Belt; W/36", 48", 52" Deck .....			6852
Trans.; Early; W/36", 48", 52" Deck .....	17334		6840
Trans.; Late; W/36", 48", 52" Deck .....	16029		6839
<b>SPP140KW</b>			
Eng. To Deck; W/36" Deck .....	35710		6702BR
Primary Drive; W/48" Deck .....	29262		6966
Traction; W/Dual Belts; W/36", 48" Deck ..	28906		②A50
Traction; W/Single Belt; W/36", 48" Deck .			6852
Trans.; Early; W/36", 48" Deck .....	17334		6840
Trans.; Late; W/36", 48" Deck .....	16029		6839
<b>SPP1250KW</b>			
Eng. To Deck; W/36" Deck .....	35710		6702BR
Traction; W/Dual Belts; W/36" Deck .....	28906		②A50
Traction; W/Single Belt; W/36" Deck .....			6852
Trans.; Early; W/36" Deck .....	17334		6840
Trans.; Late; W/36" Deck .....	16029		6839
<b>SV182</b>			
Eng. ....	12508		6534BR
<b>SV211P</b>			
Eng. ....	11887		6534BR
<b>SV212; SV212P</b>			
Eng. ....	12508		6534BR
<b>SW5BV1632; SW5KAV1532; SW5KAV1632</b>			
Deck Drive .....	5102013		6506BR
Gear Box .....	5103091		7009BR
Wheel Drive .....	5103006		6995BR

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>SW20KAV1336; SW20KAV1536</b>			
Deck Drive .....	5101313		6702BR
Hydro. Drive .....	5021770		6799BR
<b>SW20KAV1748</b>			
Deck Drive .....	5021650		6665BR
Hydro. Drive .....	5021770		6799BR
<b>SW30KAV1852</b>			
Deck Drive .....	5022148		6746BR
Pump Drive .....	5100034		7014BR
<b>SW30KAV1948</b>			
Deck Drive .....	5023496		6599BR
Pump Drive .....	5100034		7014BR
<b>SW30KAV1952; SW30KAV2052</b>			
Deck Drive .....	5022148		6746BR
Pump Drive .....	5100034		7014BR
<b>SW30KAV2061</b>			
Deck Drive .....	5100046		6878BR
Pump Drive .....	5100034		7014BR
<b>SW30KAV2152</b>			
Deck Drive .....	5022148		6746BR
Pump Drive .....	5100034		7014BR
<b>SW30KAV2461; SW30KAV2661</b>			
Deck Drive .....	5100046		6878BR
Pump Drive .....	5100034		7014BR
<b>SW35KAV2148</b>			
Deck Drive .....	5104219		6998BR
Hydro. Drive .....	5104193		7006BR
<b>SW35KAV2152</b>			
Deck Drive .....	5103392		6999BR
Hydro. Drive .....	5104193		7006BR
<b>SW35KAV2461</b>			
Deck Drive .....	5103872		6936BR
Hydro. Drive .....	5104193		7006BR
<b>V18; V21; V21P; V182; V182S</b>			
Eng. ....	12508		6534BR
<b>V210P; V210P4; V210PS; V211P; V211P4; V211PS</b>			
Eng. ....	11887		6534BR
<b>V212; V212P; V212P4; V212P5; V212PH; V212PS; V212S; V2124</b>			
Eng. ....	12508		6534BR
<b>W32080</b>			
Eng. To Blade .....	76353		6986
Traction .....	76497		6441BR
Variable Speed .....	76498		6936
<b>W32081</b>			
Eng. To Blade .....	76353		6986
Traction .....	76497		②6441BR
Variable Speed .....	76498		6936
<b>W32120; W32120K</b>			
Eng. To Blade .....	76353		6986
Traction .....	76497		6441BR
Variable Speed .....	76498		6936
<b>W32121; W32121K</b>			
Eng. To Blade .....	76353		6986
Traction .....	76497		②6441BR
Variable Speed .....	76498		6936
<b>W32122R</b>			
Eng. To Blade .....	76353		6986
Traction .....	76497		6441BR
Variable Speed .....	19203		6935
<b>W32125</b>			
Blade .....	76353		6986
Traction .....	76497		②6441BR
Variable Speed .....	76498		6936
<b>W32142BV</b>			
Eng. To Blade .....	76353		6986

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>W32142BV – Continued</b>			
Traction .....	76497		②6441BR
Variable Speed .....	19203		6935
<b>W36081</b>			
Blade .....	76353		6986
Traction .....	76497		②6441BR
Variable Speed .....	76498		6936
<b>W36120</b>			
Eng. To Blade .....	76496		6645BR
Traction .....	76497		6441BR
Variable Speed .....	76498		6936
<b>W36120K</b>			
Blade .....	76496		6645BR
Traction .....	76497		6441BR
<b>W36121; W36121K</b>			
Eng. To Blade .....	76496		6645BR
Traction .....	76497		②6441BR
Variable Speed .....	76498		6936
<b>W36122R</b>			
Eng. To Blade .....	76496		6645BR
Traction .....	19202		2/9451PB
Variable Speed .....	19203		6935
<b>W36142</b>			
Blade .....	76353		6986
Traction .....	76497		②6441BR
Variable Speed .....	76498		6936
<b>W36142BV</b>			
Eng. To Blade .....	76496		6645BR
Traction .....	19202		2/9451PB
Variable Speed .....	19203		6935
<b>W36252</b>			
Blade .....	76496		6645BR
Traction .....	76497		②6441BR
Variable Speed .....	76498		6936
<b>W48081</b>			
Blade To Blade .....	76676		6952
Eng. To Blade .....	76677		6994
Traction .....	76497		②6441BR
Variable Speed .....	76680		6554BR
<b>W48120; W48120K</b>			
Blade To Blade .....	76676		6952
Eng. To Blade .....	76677		6703BR
Traction .....	76497		6441BR
Variable Speed .....	76680		6554BR
<b>W48121; W48121K</b>			
Blade To Blade .....	76676		6952
Eng. To Blade .....	76677		6994
Traction .....	76497		②6441BR
Variable Speed .....	76680		6554BR
<b>W48122R</b>			
Blade To Blade .....	76676		6952
Eng. To Blade .....	76677		6703BR
Traction .....	19202		2/9451PB
Variable Speed .....	19203		6935
<b>W48140KS; W48140S</b>			
Blade To Blade .....	76676		6952
Eng. To Blade .....	76677		6703BR
Traction .....	76497		6441BR
Variable Speed .....	76680		6554BR
<b>W48142BV</b>			
Blade To Blade .....	76676		6952
Eng. To Blade .....	76677		6703BR
Traction .....	19202		2/9451PB
Variable Speed .....	19203		6935
<b>W321252KW</b>			
Eng. To Blade .....	76353		6986
Traction .....	76497		②6441BR
Variable Speed .....	19203		6935
<b>W361252KW</b>			
Eng. To Blade .....	76496		6645BR

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>W361252KW – Continued</b>			
Traction .....	76497		6441BR
Variable Speed .....	19202		2/9451PB
<b>W481252</b>			
Blade To Blade .....	76676		6952
Eng. To Blade .....	76677		6994
Traction .....	76497		②6441BR
Variable Speed .....	76680		6554BR
<b>W481252KW</b>			
Blade To Blade .....	76676		6952
Eng. To Blade .....	76677		6703BR
Traction .....	19202		2/9451PB
Variable Speed .....	19203		6935
<b>XP21500; XP21500KVV</b>			
Eng. ....	12353		6380
<b>Y30080; Y30120</b>			
Blade; W/30" Deck .....	15757		6969
<b>Y41120 Hvy Duty</b>			
Traction .....	76497		6441BR
<b>SOUTHLAND</b>			
<b>D1; D2; D3</b>			
Belt .....		2180	6818
<b>D4; D5</b>			
Belt .....	D356	2190	6819
<b>HW 22"; HW 24"</b>			
Belt .....	HW677	3490	6949
<b>HW 64-222</b>			
Belt; W/5 H.P. Eng. ....		3380	6938
<b>HW 64-226</b>			
Belt .....		3380	6938
<b>SP2-22</b>			
Belt; W/B. & S. Eng. ....	SP9413	2390	6839
Belt; W/Tecumseh Eng. ....	SP2700	2380	6838
<b>SP2-211</b>			
Belt .....		2230	6823
<b>SP2-213</b>			
Belt .....	SP9413	2390	6839
<b>SP2-241</b>			
Belt; W/23" Belt O.C. ....		2230	6823
Belt; W/39" Belt O.C. ....	SP9413	2390	6839
<b>SP9-201</b>			
Belt .....	SP9413	2390	6839
<b>SP9-201GP</b>			
Belt .....		2230	6823
<b>SP9-204; SP9-205; SP9-221; SP9-224; SP9-225</b>			
Belt .....	SP9413	2390	6839
<b>SP9-241</b>			
Belt .....		2410	6841
<b>SP9-244; SP9-245</b>			
Belt .....	R8371	2410	6841
<b>SP10-22</b>			
Belt .....	SP9413	2390	6839
<b>SPEIGEL</b>			
<b>121-450</b>			
Belt .....	7540935	2310	6831
<b>122-550; 123-550; 124-550</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>128-455</b>			
Belt .....	7540935	2310	6831





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SPRINGFIELD</b>			
<b>60A; 60D; 60DE</b>			
Blade - Left .....	60D56	2310	6831
Blade - Right .....	60D57	2300	6830
<b>SUNBEAM CORP.</b>			
<b>R121; R121A; R221; R321; R321A</b>			
Belt .....	484620	1280	6728
<b>SUNSHINE</b>			
<b>8212</b>			
Blade .....			6848
<b>8813</b>			
Blade .....		2500	6850
Drive; W/22" Belt O.C. ....		2220	6822
Drive; W/26" Belt O.C. ....	5600	1260	6726
<b>82125</b>			
Blade .....			6848
<b>88135</b>			
Blade .....		2500	6850
Drive; W/22" Belt O.C. ....		2220	6822
Drive; W/26" Belt O.C. ....	5600	1260	6726
<b>A21SP</b>			
Drive; W/22" Belt O.C. ....	S333		6822
Drive; W/25" Belt O.C. ....	S334		6825
<b>E-Z Roll 22; E-Z Roll 22SP; E-Z Roll 24; E-Z Roll 24SP</b>			
Drive .....	S2110		6730
<b>NS421SP</b>			
Drive; W/22" Belt O.C. ....	S333		6822
Drive; W/25" Belt O.C. ....	S334		6825
<b>NS426SP</b>			
Drive; W/22" Belt O.C. ....	S333		6822
Drive; W/23" Belt O.C. ....	S336		6823
Drive; W/30" Belt O.C. ....			6830
<b>SA25SP</b>			
Drive .....	S333		6822
<b>TORO</b>			
<b>24" Self-Propelled</b>			
Forward .....	WW5403A		6929
Reverse .....	27156	2340	
<b>325-D Diesel</b>			
Alt. ....	REMF1370	7370	
Blade .....	539660		6539BR
Drive .....	210890		6972
Fan .....	435910	7516	
<b>10118; 10119; 10128; 10129</b>			
Belt .....	27143	2230	6823
<b>10413; 10423</b>			
Drive .....	27157	1250	6725
<b>12012; 12112; 12113</b>			
Blade .....	27191		6948
Drive .....	34733	3290	6929
<b>14111</b>			
Drive .....	27138	3290	
<b>16000; 16009; 16035; 16067; 16073; 16077; 16106; 16111; 16113; 16155</b>			
Drive .....	54505		6469BR
<b>16165; 16169; 16173; 16212; 16212B; 16212C; 16212CG; 16212W; 16212WG; 16222</b>			
Drive .....	54505		6469BR
<b>16233; 16240; 16255</b>			
Drive .....	54505		6469BR
<b>16264</b>			
Drive; Ser. No. 7000001 & After .....	54505		6469BR
<b>16268; 16273</b>			
Drive .....	54505		6469BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>16277</b>			
Drive; Ser. No. 7000001 & After .....	54505		6469BR
<b>16287; 16297; 16297C; 16299; 16299C; 16300; 16310; 16320; 16380; 16390</b>			
Drive .....	54505		6469BR
<b>16401; 16402; 16404; 16411; 16551; 16575; 16655</b>			
Drive .....	54505		6469BR
<b>16756</b>			
Drive .....	249730		6736
<b>16770; 16771; 16775; 16776; 16780</b>			
Drive .....	54505		6469BR
<b>16785</b>			
Drive; Ser. No. 5000001 & After .....	54505		6469BR
<b>16793</b>			
Drive; Ser. No. 8000001 & After .....	54505		6469BR
<b>16870</b>			
Belt .....	368070	1340	6734
<b>17601; 18005; 18010; 18015; 18060; 18085; 18095</b>			
Drive .....	54505		6469BR
<b>18110</b>			
Belt .....	37274		6732
<b>18112; 18113</b>			
Blade .....	31183	1170	6717
Traction .....	31182		6730
<b>18120</b>			
Belt .....	37274		6732
<b>18122; 18123</b>			
Blade .....	31183	1170	6717
Traction .....	31182		6730
<b>18210; 18220</b>			
Belt .....	37274		6732
<b>18400</b>			
Drive .....	54505		6469BR
<b>19120</b>			
Belt .....	37274		6732
<b>19122; 19123</b>			
Blade .....	31183	1170	6717
Traction .....	31182		6730
<b>19220</b>			
Belt .....	37274		6732
<b>19271; 19367; 19472; 19500</b>			
Drive .....	54505		6469BR
<b>20106; 20107</b>			
Blade .....	420884		6544BR
Drive .....	623900		6735
<b>20120</b>			
Belt .....	37274		6732
<b>20122; 20123</b>			
Blade .....	31183	1170	6717
Traction .....	31182		6730
<b>20199; 20200</b>			
Drive - Upper .....	121-5765		6453BR
<b>20210; 20211</b>			
Blade .....	420884		6544BR
Drive .....	623900		6735
<b>20212; 20213</b>			
Belt; W/17" Belt O.C. ....	31183	1170	6717
Belt; W/30" Belt O.C. ....	31182		6730
Belt; W/47" Belt O.C. ....	34577		6847
<b>20214; 20216; 20218</b>			
Drive .....	623900		6735

Lawn & Garden Equipment

# WALK BEHIND MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>				<b>TORO - Continued</b>			
<b>20219</b>				<b>20442; 20444; 20454; 20462; 20463; 20464</b>			
Blade .....	420884		6544BR	Drive .....	930232		6732
Drive .....	623900		6735	<b>20465; 20466</b>			
<b>20221</b>				Blade .....	420884		6544BR
Belt .....	37274		6732	Drive .....	623900		6735
<b>20223; 20227</b>				<b>20472; 20473; 20474</b>			
Drive .....	54505		6469BR	Drive .....	623900		6735
<b>20310</b>				<b>20475; 20476; 20482; 20483; 20487</b>			
Belt; W/32" Belt O.C. ....	37274		6732	Blade .....	420884		6544BR
Belt; W/47" Belt O.C. ....	34577		6847	Drive .....	623900		6735
<b>20311</b>				<b>20511</b>			
Blade .....	34577		6847	Traction .....	660210		6734
Drive .....	54505		6469BR	<b>20517</b>			
<b>20313</b>				Drive .....	249730		6736
Blade .....	34577		6847	<b>20550</b>			
Traction .....	54505		6469BR	Drive .....	230220		6737
<b>20314; 20316</b>				<b>20555</b>			
Drive .....	110-9429		6732	Drive .....	54505		6469BR
<b>20320; 20321; 20322</b>				<b>20561</b>			
Drive .....	623900		6735	Traction .....	623900		6735
<b>20324; 20325</b>				<b>20562</b>			
Blade .....	420884		6544BR	Drive .....	249730		6736
Drive .....	623900		6735	<b>20564</b>			
<b>20327B; 20328B</b>				Traction .....	660210		6734
Drive .....	623900		6735	<b>20571</b>			
<b>20332</b>				Drive .....	54505		6469BR
Drive .....	115-4669		6733	<b>20575</b>			
<b>20333</b>				Drive .....	249730		6736
Blade Drive .....	110-1790		6822	<b>20576</b>			
Drive .....	115-4669		6733	Drive .....	420880		6823
<b>20334; 20337</b>				<b>20584</b>			
Drive .....	115-4669		6733	Drive; Ser. No. 4000001 Thru 600000 .....	420881		6823
<b>20339</b>				Drive; Ser. No. 6000001 .....	420883		6824
Drive .....	117-1018		6732	Drive; W/34" Belt O.C. ....	368070		6734
<b>20340</b>				<b>20600</b>			
Drive .....	912258		6735	Drive .....	54505		6469BR
<b>20353</b>				<b>20620</b>			
Drive .....	719450		6732	Drive .....	368070		6734
<b>20370; 20371</b>				<b>20622</b>			
Drive .....	117-1018		6732	Blade .....	420884		6544BR
<b>20372</b>				Drive .....	623900		6735
Drive .....	115-4669		6733	<b>20624</b>			
<b>20373</b>				Blade Brake .....	420880		6823
Blade Drive .....	110-1790		6822	<b>20631; 20632</b>			
Drive .....	115-4669		6733	Drive .....	623900		6735
<b>20374</b>				<b>20644; 20657</b>			
Drive .....	115-4669		6733	Drive .....	249730		6736
<b>20376</b>				<b>20660</b>			
Blade Drive .....	110-1790		6822	Drive .....	230220		6737
Drive .....	115-4669		6733	<b>20661</b>			
<b>20377; 20378</b>				Blade .....	420880		6823
Drive .....	117-1018		6732	Traction .....	368070		6734
<b>20383</b>				<b>20666</b>			
Blade .....	110-1790		6822	Traction .....	623900		6735
<b>20432; 20434</b>				<b>20667</b>			
Drive .....	912258		6735	Blade .....	420884		6544BR
<b>20436; 20437</b>				Drive .....	623900		6735
Drive .....	623900		6735	<b>20668</b>			
<b>20438; 20438WF; 20439; 20439WF</b>				Drive .....	623900		6735
Blade .....	420884		6544BR	<b>20671</b>			
Drive .....	623900		6735	Traction .....	368070		6734
<b>20440</b>				<b>20672</b>			
Drive .....	230220		6737	Blade .....	420880		6823



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>20672 – Continued</b>			
Traction .....	368070		6734
<b>20673</b>			
Drive .....	249730		6736
<b>20674; 20675; 20676</b>			
Traction .....	368070		6734
<b>20677</b>			
Drive .....	623900		6735
<b>20680</b>			
Drive; W/35" Belt O.C. ....	623900		6735
Traction; Ser. No. 60000101 Thru 6002200; W/34" Belt O.C. ....	368070		6734
<b>20684</b>			
Belt; W/35" Belt O.C. ....	623900		6735
Drive; Ser. No. 6000001 Thru 6002200 ...	420881		6823
Traction; Ser. No. 60000101 Thru 6002200; W/34" Belt O.C. ....	368070		6734
<b>20692</b>			
Traction .....	623900		6735
<b>20730; 20740; 20750</b>			
Drive .....	249730		6736
<b>20755</b>			
Belt; 1980-1979 .....	249730	1360	6736
Drive; 1982-1981 .....	54505		6469BR
<b>20761B; 20763B; 20764B; 20764BC; 20766B; 20766BC; 20767; 20767B; 20768; 20768B</b>			
Drive .....	623900		6735
<b>20770; 20771</b>			
Drive .....	54505		6469BR
<b>20773</b>			
Blade .....	420880		6823
Drive .....	54505		6469BR
<b>20775</b>			
Drive .....	368070		6734
<b>20777</b>			
Traction .....	623900		6735
<b>20785; 20790</b>			
Drive .....	368070		6734
<b>20801BC; 20806B; 20806BC; 20808B; 20820BC; 20821B</b>			
Drive .....	719450		6732
<b>20900B; 20901B</b>			
Drive .....	718500		6733
<b>20904BC</b>			
Drive .....	719450		6732
<b>20905; 20905B</b>			
Drive .....	718500		6733
<b>20907B; 20908B; 20908BC</b>			
Drive .....	719450		6732
<b>20910; 20911B</b>			
Drive .....	718500		6733
<b>20914B</b>			
Drive .....	719450		6732
<b>20915</b>			
Drive .....	718500		6733
<b>20916B</b>			
Drive; W/32" Belt O.C. ....	719450		6732
Drive; W/33" Belt O.C. ....	718500		6733
<b>20917B</b>			
Drive .....	719450		6732
<b>20920; 20920B; 20921B</b>			
Drive .....	718500		6733

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>20922B; 20922BC; 20923B</b>			
Drive .....	719450		6732
<b>20925; 20925B; 20927B</b>			
Drive .....	718500		6733
<b>20928B; 20928BC; 20929B</b>			
Drive .....	719450		6732
<b>21003; 21004; 21073</b>			
Drive .....	54505		6469BR
<b>21100</b>			
Drive .....	37274		6732
<b>21101; 21102; 21103; 21104; 21172; 21273; 21373; 21473; 21610; 21647</b>			
Drive .....	54505		6469BR
<b>21658; 21666; 21711; 21727; 21738</b>			
Drive .....	54505		6469BR
<b>22010</b>			
Drive .....	499100		6730
<b>22020</b>			
Traction .....	368070		6734
<b>22035; 22036; 22037B; 22037BC; 22038B; 22040; 22042</b>			
Drive .....	368070		6734
<b>22043; 22044BC; 22045; 22045B; 22142</b>			
Blade .....	420884		6544BR
Drive .....	368070		6734
<b>22150</b>			
Drive .....	368070		6734
<b>22151; 22153BC; 22154; 22154B; 22157; 22162; 22172; 22173</b>			
Blade .....	420884		6544BR
Drive .....	368070		6734
<b>22200; 22210</b>			
Drive - Lower .....	116-7116		7003BR
Drive - Upper .....	121-5765		6453BR
<b>22290</b>			
Trans. ....	125-8395		6619BR
<b>22295</b>			
Trans. ....	125-1011		6734
<b>22296</b>			
Blade Drive .....	110-1790		6822
Trans. ....	125-1011		6734
<b>22297</b>			
Trans. ....	125-1011		6734
<b>22298</b>			
Blade Drive .....	110-1790		6822
Trans. ....	125-1011		6734
<b>22580; 22621; 22622; 22623</b>			
Traction .....	660210		6734
<b>22625BG</b>			
Drive .....	368070		6734
<b>22685</b>			
Traction .....	660210		6734
<b>22700; 22700B; 22700BC; 22701B</b>			
Drive .....	368070		6734
<b>23100; 23123 Whirlwind H/D; 23144; 23177</b>			
Blade .....	36593		6841
<b>23200</b>			
Blade .....	38095		6834
Traction .....	38093		6826
<b>23201; 23205 Whirlwind</b>			
Blade .....	38095		6834
Drive .....	32733		6825

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>23267 25"</b>			
Blade; W/33" Belt O.C. ....	70354		6833
Blade; W/34" Belt O.C. ....	38095		6834
Drive .....	32733		6825
Traction .....	38093		6826
<b>23267 Commercial</b>			
Blade .....	32733		6825
Traction .....	70354		6833
<b>23300</b>			
Blade .....	38166		6840
Drive .....	38093		6826
<b>23301</b>			
Blade .....	38166		6840
Traction .....	51583		6824
<b>23301 34"</b>			
Blade; W/24" Belt O.C. ....	51583		6824
Blade; W/26" Belt O.C. ....	38093		6826
Drive .....	38166		6840
<b>23310</b>			
Blade .....	38166		6840
Drive .....	51583		6824
<b>23450</b>		2610	
Blade .....	27199		
<b>24003</b>		2610	
Blade .....	27199		
Drive .....	271100		6852
<b>26562</b>			
Blade .....	655740		6824
<b>26620B; 26620BF; 26620BG</b>			
Drive .....	660210		6734
<b>26621; 26621B; 26622; 26623; 26624</b>			
Blade .....	655740		6824
Drive .....	660210		6734
<b>26624C; 26625B</b>			
Drive .....	660210		6734
<b>26626</b>			
Blade .....	655740		6824
Drive .....	660210		6734
<b>26630B</b>			
Drive .....	660210		6734
<b>26630BC</b>			
Drive; 1994 .....	660210		6734
Drive; 1995 .....	368070		6734
<b>26630BG</b>			
Drive .....	660210		6734
<b>26631B; 26631BC</b>			
Blade .....	655740		6824
Drive .....	660210		6734
<b>26632B</b>			
Drive .....	368070		6734
<b>26633B</b>			
Blade .....	655740		6824
Drive .....	368070		6734
<b>26635B</b>			
Drive .....	660210		6734
<b>26635BC</b>			
Drive; 1994 .....	660210		6734
Drive; 1995 .....	368070		6734
<b>26635BG</b>			
Drive .....	660210		6734
<b>26636B</b>			
Drive .....	368070		6734
<b>26640B; 26640BC; 26641; 26642; 26643B</b>			
Drive .....	660210		6734

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>26651</b>			
Traction .....	660210		6734
<b>26680; 26680WG</b>			
Drive .....	660210		6734
<b>26682; 26683; 27500; 27501; 27502</b>			
Blade .....	655740		6824
Drive .....	660210		6734
<b>30072</b>			
Trans. ....	26-9671		6839
<b>30074</b>			
Blade Drive .....	110-6953		6819BR
Eng. To Deck .....	110-6954		6839BR
Trans. ....	105-5668		7008BR
<b>30076</b>			
Blade Drive .....	110-6972		6714BR
Eng. To Deck .....	110-6973		6402BR
Trans. ....	105-5668		7008BR
<b>30078</b>			
Blade Drive .....	108-2716		6821BR
Eng. To Deck .....	108-2715		6840BR
Trans. ....	105-5668		7008BR
<b>30079</b>			
Blade Drive .....	108-2694		6650BR
Eng. To Deck .....	108-2693		6573BR
Trans. ....	105-5668		7008BR
<b>30094</b>			
Blade Drive .....	110-6953		6819BR
Eng. To Deck .....	110-6954		6839BR
Trans. ....	105-5668		7008BR
<b>30096</b>			
Blade Drive .....	110-6972		6714BR
Eng. To Deck .....	110-6973		6402BR
Trans. ....	105-5668		7008BR
<b>30098</b>			
Blade Drive .....	108-2716		6821BR
Eng. To Deck .....	108-2715		6840BR
Trans. ....	105-5668		7008BR
<b>30099</b>			
Blade Drive .....	108-2694		6650BR
Eng. To Deck .....	108-2693		6573BR
Trans. ....	105-5668		7008BR
<b>30102</b>			
Eng. To Trans. ....	269670		6840
<b>30103</b>			
Drive .....	514290		6442BR
Eng. To Trans. ....	269670		6840
<b>30106</b>			
Deck Drive .....	542750		6838BR
Drive .....	514290		②6442BR
Traction .....	269670		6840
<b>30108</b>			
Blade .....	513530		6809BR
Deck .....	513600		6863
Drive .....	514290		6442BR
Trans. ....	269670		6840
<b>30111</b>			
Cross Deck .....	271160		6571BR
Deck Drive .....	542750		6838BR
Drive .....	514290		6442BR
Traction .....	269670		6840
<b>30112</b>			
Deck .....	542750		6838BR
Drive .....	514290		②6442BR
Traction .....	269670		6840
<b>30113</b>			
Cross Deck .....	271160		6571BR
Deck Drive .....	542750		6838BR
Drive .....	514290		6442BR

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>30113 - Continued</b>			
Trans. ....	269670		6840
<b>30114; 30115</b>			
Deck .....	542750		6838BR
Drive .....	514290		②6442BR
Traction .....	269670		6840
<b>30116</b>			
Cross Deck .....	271160		6571BR
Deck Drive .....	542750		6838BR
Drive .....	514290		6442BR
Traction .....	269670		6840
<b>30117</b>			
Deck .....	542750		6838BR
Drive .....	514290		②6442BR
Traction .....	269670		6840
<b>30125</b>			
Eng. To Trans. ....	269670		6840
<b>30126</b>			
Blade .....	513530		6809BR
<b>30127</b>			
Blade .....	542750		6838BR
<b>30133</b>			
Blade .....	542751		6969
<b>30136</b>			
Blade; Ser. No. 7000001 & After .....	542750		6838BR
Eng. To Trans. ....	269670		6840
<b>30140</b>			
Deck .....	1403171		6665BR
Wheel Drive .....	1-323631		6664BR
<b>30144</b>			
Cross Deck .....	271160		6571BR
Deck Drive .....	542750		6838BR
Eng. To Trans. ....	269670		6840
<b>30152</b>			
Cross Deck .....	271160		6571BR
Deck Drive .....	557660		6971
Eng. To Trans. ....	269670		6840
<b>30155 Pro Line 32</b>			
Trans.; W/12.5 H.P., 4-Speed Eng. ....	269670		6840
<b>30156; 30157</b>			
Traction .....	269670		6840
<b>30165; 30166; 30170; 30175; 30176</b>			
Deck .....	542750		6838BR
Drive .....	514290		②6442BR
Traction .....	269670		6840
<b>30180</b>			
Deck; W/36", 44" Deck .....	542750		6838BR
Deck; W/52" Deck .....	557660		6971
Drive .....	514290		②6442BR
Traction .....	26-9671		6839
<b>30181</b>			
Deck; W/36", 44" Deck .....	542750		6838BR
Deck; W/52" Deck .....	557660		6971
Drive .....	514290		②6442BR
Traction .....	269670		6840
<b>30185; 30186; 30190</b>			
Drive .....	824110		6847
<b>30280</b>			
Blade Drive .....	108-6645		6849BR
<b>30284</b>			
Blade Drive .....	110-6953		6819BR
Eng. To Deck .....	110-6954		6839BR
Hydro. ....	110-5049		7052BR
<b>30286</b>			
Blade Drive .....	110-6972		6714BR
Eng. To Deck .....	110-6973		6402BR
Hydro. ....	110-5049		7052BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>30288</b>			
Blade Drive .....	108-2716		6821BR
Eng. To Deck .....	108-2715		6840BR
Hydro. ....	110-5049		7052BR
<b>30289</b>			
Blade Drive .....	108-2694		6650BR
Eng. To Deck .....	108-2693		6573BR
Hydro. ....	110-5049		7052BR
<b>30484</b>			
Blade Drive .....	110-6953		6819BR
Eng. To Deck .....	110-6954		6839BR
Hydro. ....	110-5049		7052BR
<b>30486</b>			
Blade Drive .....	110-6972		6714BR
Eng. To Deck .....	110-6973		6402BR
Hydro. ....	110-5049		7052BR
<b>30488</b>			
Blade Drive .....	108-2716		6821BR
Eng. To Deck .....	108-2715		6840BR
Hydro. Drive .....	110-5049		7052BR
<b>30489</b>			
Blade Drive .....	108-2694		6650BR
Eng. To Deck .....	108-2693		6573BR
Hydro. Drive .....	110-5049		7052BR
<b>30494</b>			
Blade Drive .....	110-6953		6819BR
Eng. To Deck .....	110-6954		6839BR
Hydro. ....	110-5049		7052BR
<b>30496</b>			
Blade Drive .....	110-6972		6714BR
Eng. To Deck .....	110-6973		6402BR
Hydro. ....	110-5049		7052BR
<b>30498</b>			
Blade Drive .....	108-2716		6821BR
Eng. To Deck .....	108-2715		6840BR
Hydro. ....	110-5049		7052BR
<b>30499</b>			
Blade Drive .....	108-2694		6650BR
Eng. To Deck .....	108-2693		6573BR
Hydro. ....	110-5049		7052BR
<b>30632</b>			
Blade Drive .....	1-323745		6506BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323744		②6487BR
<b>30634</b>			
Blade Drive .....	110-4886		6812BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323631		6664BR
<b>30638</b>			
Blade Drive .....	110-0543		7048BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323631		6664BR
<b>30672</b>			
Blade Drive .....	1-323745		6506BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323744		6487BR
<b>30674</b>			
Blade Drive .....	110-4886		6812BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323631		6664BR
<b>30678</b>			
Blade Drive .....	110-0543		7048BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323631		6664BR
<b>30682</b>			
Blade Drive .....	1-323745		6506BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323744		6487BR

②Two Required



**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>30684</b>			
Blade Drive .....	110-4886		6812BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323631		6664BR
<b>30686</b>			
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323631		6664BR
<b>30688</b>			
Blade Drive .....	110-0543		7048BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323631		6664BR
<b>30692</b>			
Blade Drive .....	1-323745		6506BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323744		6487BR
<b>30694</b>			
Blade Drive .....	110-4886		6812BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323631		6664BR
<b>30696</b>			
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323631		6664BR
<b>30698</b>			
Blade Drive .....	110-0543		7048BR
Trans. ....	1-323630		7025BR
Wheel Drive .....	1-323631		6664BR
<b>30934</b>			
Deck Drive .....	108-6644		6866BR
Hydro. ....	106-2740		6552BR
<b>30938</b>			
Deck Drive .....	110-0543		7048BR
Hydro. ....	106-2740		6552BR
<b>30984</b>			
Deck Drive .....	108-6644		6866BR
Hydro. ....	106-2740		6552BR
<b>30986</b>			
Hydro. ....	106-2740		6552BR
<b>30988</b>			
Deck Drive .....	110-0543		7048BR
Hydro. ....	106-2740		6552BR
<b>30989</b>			
Hydro. ....	106-2740		6552BR
<b>59111</b>			
Deck .....	285250		6853
Traction .....	282650		A100
<b>78355</b>			
Deck .....	106125		6889
Drive .....	108834		6898
<b>90506; 90526B</b>			
Drive .....	718500		6733
<b>206912</b>			
Drive .....	623900		6735
<b>573575</b>			
Deck .....	285250		6853
Traction .....	282650		A100
<b>660210</b>		1340	6734
Belt .....	368070		
<b>Commercial 103; Commercial 110; Commercial 111; Commercial 112; Commercial 116</b>			
Deck .....	542750		6838BR
Traction .....	269670		6840
<b>Commercial S.P. 25"</b>			
Blade; W/33" Belt O.C. ....	70354		6833
Blade; W/34" Belt O.C. ....	38095		6834
Drive .....	32733		6825
Traction .....	38093		6826

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>Fiesta Guardian 21" 20223; Fiesta Guardian 21" 20227; Fiesta Guardian 21" 20337; Fiesta Guardian 21" 20555; Fiesta Guardian 21" 20571; Fiesta Guardian 21" 20600; Fiesta Guardian 21" 20771; Fiesta Guardian 21" 21073; Fiesta Guardian 21" 21101; Fiesta Guardian 21" 21102</b>			
Drive .....	54505		6469BR
<b>Fiesta Guardian 21" 21103; Fiesta Guardian 21" 21104; Fiesta Guardian 21" 21172; Fiesta Guardian 21" 21273; Fiesta Guardian 21" 21373; Fiesta Guardian 21" 21473; Fiesta Guardian 21" 21610; Fiesta Guardian 21" 21647</b>			
Drive .....	54505		6469BR
<b>Grassmaster 21" 20517</b>			
Belt .....	249730	1360	6736
<b>Grassmaster 21" 20550</b>			6737
Belt .....			
<b>Grassmaster 21" 20562; Grassmaster 21" 20575; Grassmaster 21" 20644; Grassmaster 21" 20657</b>			
Belt .....	249730	1360	6736
<b>Grassmaster 21" 20660</b>			6737
Belt .....			
<b>Grassmaster 21" 20673; Grassmaster 21" 20690; Grassmaster 21" 20750</b>			
Belt .....	249730	1360	6736
<b>Greensmaster</b>			
Belt; W/17" Deck .....	27115	2360	6836
Drive; W/27" Belt O.C.; W/21" Deck .....	32251		6827
Drive; W/28" Belt O.C.; W/21" Deck .....	27113		6828
<b>Greensmaster 800; Greensmaster 1000; Greensmaster 1600</b>			
Clutch .....	92-9218		②6821
<b>Greensmower</b>			
Drive; W/21" Deck .....	27113		6828
Reel Drive; W/21" Deck .....	2714		6830
<b>Groundmaster 117</b>			
Eng. To J.S. ....	541380		6874
J.S. To Deck .....	541360		6849
<b>Groundmaster 120</b>			
Eng. To J.S. ....	541380		6874
Fan .....	541390		6755BR
<b>Groundmaster 322-D</b>			
Alt .....	REMF1370	7370	
Blade .....	539660		6539BR
Drive .....	210890		6972
Fan .....	435910	7516	
<b>Groundmaster 327</b>			
Alt. & Gov. ....	258340		6733
Fan & Idler .....	266660	7265	
<b>Guardian 19" 18171; Guardian 19" 18257; Guardian 19" 19273</b>			
Belt .....	85660		6729
<b>HMR 1200; HMR 1600</b>			
Belt; W/44" Deck .....	576990		6882
Drive .....	542750		6838BR
<b>Pro Line 117</b>			
J.S. To Deck; W/36", 44" Deck .....	542750		6838BR
J.S. To Deck; W/52" Deck .....	541360		6849
<b>Pro Line 118</b>			
Eng. To J.S. ....	541380		6874
J.S. To Deck; W/36", 44" Deck .....	542750		6838BR
<b>Pro Line 180; Pro Line 185</b>			
Eng. To Deck; W/36", 44" Deck .....	542750		6838BR

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>Pro Line 180; Pro Line 185 – Continued</b>			
Eng. To Deck; W/52" Deck .....	557660		6971
<b>Professional 1; Professional 2; Professional 3</b>			
Countershaft .....	27110	3310	
<b>Sportlawn</b>			
Belt; W/17" Deck .....	2716	2180	6818
Belt; W/18", 21" Deck .....	27117	2210	6821
Belt; W/20" Deck .....	27143	2230	6823
<b>Whirlwind</b>			
Belt; W/32" Belt O.C. ....	37274		6732
Drive .....	54505		6469BR
<b>Whirlwind Hevi-Duty 23205</b>			
Blade; W/33" Belt O.C. ....	70354		6833
Blade; W/34" Belt O.C. ....	38095		6834
Drive .....	32733		6825
Traction .....	38093		6826
<b>Whirlwind II Deluxe 21" 21666; Whirlwind II Deluxe 21" 21711; Whirlwind II Deluxe 21" 21727; Whirlwind II Deluxe 21" 21738</b>			
Drive .....	54505		6469BR
<b>TRACTOR SUPPLY</b>			
<b>44-186</b>			
Blade .....	7540109		6843
Traction; W/31" Belt O.C. ....	7540121		6831
Traction; W/32" Belt O.C. ....	7540104		6832
<b>44-1822</b>			
Drive .....	7540114		6824
<b>44-1825</b>			
Traction .....	7540114		6824
<b>44-1831</b>			
Blade .....	7540116		6842
<b>44-1841</b>			
Traction .....	7540242		6832
<b>44-1842; 44-1843</b>			
Traction .....	7540114		6824
<b>44-1845</b>			
Blade .....	7540109		6843
Traction .....	7540104		6832
<b>44-1848</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>120-270</b>			
Drive .....	7540114		6824
<b>120-550; 122-550; 123-550</b>			
Blade .....	7540109		6843
Traction; W/31" Belt O.C. ....	7540121		6831
Traction; W/32" Belt O.C. ....	7540104		6832
<b>230-131</b>			
Traction .....	7540242		6832
<b>550-131</b>			
Blade .....	7540109		6843
Traction .....	7540104		6832
<b>TRAIL MATE</b>			
<b>7002</b>			
Blade .....			6827
Drive .....			6950
Wheel Drive .....			6822
<b>7004; 7006</b>			
Blade; W/53" Belt O.C. ....			6953
Blade; W/54" Belt O.C. ....			6954
Drive .....			6829
<b>E-Z Roll</b>			
Eng. To Deck .....			6953
J.S. ....			6829

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TROY BILT</b>			
<b>12-A2BU711; 12-A2BU766; 12A-A25S011; 12A-A25S066; 12A-A25U211; 12A-A25U711; 12A-A25U766; 12A-A26M011; 12A-A26M066; 12A-A26N211</b>			
Drive .....	954-04259A		6734
<b>12ABD3A3766; 12ABD3BV711; 12ABD3BV766; 12ABD3BY711; 12ABD3BZ711; 12ABD35U766; 12ACC3BJ011; 12ACC3BJ066; 12ACC3BJ766; 12ACC35S066</b>			
Drive .....	95404282		6731
<b>12ACC35S766</b>			
Drive .....	95404282		6731
<b>12AE76JU011; 12AE76JU711</b>			
Drive .....	95404145A		6864
Eng. To Deck .....	954-04139		6976BR
<b>12AE763Z011</b>			
Eng. To Deck .....	954-04139		6976BR
Hydro. Drive .....	95404145A		6864
<b>12AGA2BJ011; 12AGA2BJ711; 12AGA25S011; 12AGA25S066; 12AGA25S711; 12AGA25S766; 12AGA26E011; 12AGA26E066; 12AGA26G011; 12AGA26G066</b>			
Drive .....	954-04260		6734
<b>12AGA26G211; 12AGA26G711; 12AGA26G766</b>			
Drive .....	954-04260		6734
<b>12AKC2A3766; 12AKC3A3766; 12AKC3BV711; 12AKC3BV766; 12AKC32N766; 12AKC35U766; 12AKD6BZ711; 12AKD39B011; 12AKD39B066; 12AKD39C211</b>			
Drive .....	95404282		6731
<b>12AKD39C766; 12ALC35S766</b>			
Drive .....	95404282		6731
<b>12AVB2A3711; 12AVB2A3766; 12AVB2AQ711; 12AVB2BV711; 12AVB2BV766; 12AVB22J766; 12AVB25S011; 12AVB25S066; 12AVB25U211; 12AVB25U711</b>			
Drive .....	954-04260		6734
<b>12AVB25U766; 12AVB26M011; 12AVB26M066; 12AVB26N211</b>			
Drive .....	954-04260		6734
<b>12AVC35U766</b>			
Drive .....	95404282		6731
<b>23AAAA8X711</b>			
Deck Drive .....	954-05103		6975BR
Eng. ....	954-05070		6827
<b>35B; 35C</b>			
Drive .....			6844
<b>36-7B; 36-7C1; 36-7D; 36-8B</b>			
Drive .....	170746		6749
<b>36B</b>			
Drive .....	170738		6747
<b>86C; 86D; 87C; 87D</b>			
Drive .....	170829		6738
<b>92; 92-929</b>			
Drive .....	170399		6844
<b>92B; 92D; 92E</b>			
Drive .....	170647		6844
<b>98; 98-229</b>			
Drive .....	170399		6844
<b>367-D</b>			
Drive .....	170746		6749
<b>11368</b>			
Blade; W/8 H.P. Eng.; W/24" Blade .....			6857

Lawn & Garden Equipment

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TROY BILT - Continued</b>			
<b>Gardenway</b>			
Reel Drive .....	1060		6819
<b>Hi Wheel I; Hi Wheel II</b>			
Blade .....	T236321		6857
<b>Trailblazer 1; Trailblazer 2; Trailblazer 3; Trailblazer 4; Trailblazer 5</b>			
Cutter Bar .....	P406416		6842
<b>Tuff Cut 1; Tuff Cut 2</b>			
Blade .....			6857
Drive .....	T239661		6736
<b>TRU-TEST</b>			
<b>JA-210-HW; TA-210-HW</b>			
Blade .....			6940
<b>UNICO</b>			
<b>118-500</b>			
Belt .....	7540116	2420	6842
<b>125-450</b>			
Traction .....	7540935	2310	6831
<b>128-220; 128-230</b>			
Belt .....	7540242	2320	6832
<b>128-270</b>			
Belt .....	7540114	2240	6824
<b>128-272</b>			
Traction .....	7540163		6828
<b>128-550</b>			
Blade .....	7540109		6843
Trans. ....	7540121		6831
<b>158-518</b>			
Belt .....	7540156		6820
<b>270-015</b>			
Belt .....	7540114	2240	6824
<b>510-015; 520-015</b>			
Belt .....	7540100	2180	6818
<b>1225</b>			
Belt .....	7540116	2420	6842
<b>2180; 2181</b>			
Belt .....	7540126		6820
<b>2201-71</b>			
Traction .....	7540163		6828
<b>2211; 2211-01; 2211-41; 2211-71; 2211-91; 2212</b>			
Belt .....	7540114	2240	6824
<b>2222</b>			
Blade .....	7540109		6843
Trans. ....	7540121		6831
<b>2223; 2225</b>			
Traction .....	7540239	2290	6829
<b>2227-41; 2227-51; 2227-61; 2227-91</b>			
Traction .....	7540935	2310	6831
<b>2228-81-1</b>			
Belt .....	7540114	2240	6824
<b>2251</b>			
Blade .....	7540114	2240	6824
Drive .....	7540143		6728
<b>2251-01; 2251-3; 2251-71; 2251-91; 2261-41</b>			
Blade .....	7540144	3550	6955
Drive .....	7540143		6728
<b>UNITED FARM TOOLS, INC.</b>			
<b>884</b>			
Spindle; W/40" Mower .....	1272		3V375

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>UNITED FARM TOOLS, INC. - Continued</b>			
<b>885</b>			
Spindle; W/60" Mower .....	1501		6965
<b>VEMCO</b>			
<b>HP22; SP22</b>			
Belt .....			6834
<b>WEST POINT</b>			
<b>VC; VC-1</b>			
Belt; W/36" Belt O.C. ....	9081	3360	6936
Belt; W/46" Belt O.C. ....	9065	3460	6946
<b>VC-2A; VC-3</b>			
Eng. ....		3440	6944
Reel Drive .....	9127	3500	6950
<b>VC-3A</b>			
Belt; W/42" Belt O.C. ....	9793	3420	6942
Belt; W/50" Belt O.C. ....	9127	3500	6950
<b>VC-4</b>			
Belt .....	9127	3500	6950
<b>VC-4A</b>			
Belt; W/42" Belt O.C. ....	9793	3420	6942
Belt; W/50" Belt O.C. ....	9127	3500	6950
<b>VC-6</b>			
Belt .....	9382	3370	6937
<b>VC-12</b>			
Belt .....	9202	3290	6929
<b>VC-13</b>			
Belt; W/28" Belt O.C. ....	9596	2280	6828
Belt; W/29" Belt O.C. ....	9587	2290	6829
<b>VC-18</b>			
Belt .....		2280	6828
<b>VC-20</b>			
Belt .....	9631	2300	6830
<b>Veri-Cut</b>			
Belt; W/36" Belt O.C. ....	9081	3360	6936
Belt; W/44" Belt O.C. ....		3440	6944
Belt; W/46" Belt O.C. ....	9065	3460	6946
<b>VG-1</b>			
Belt; W/42" Belt O.C. ....	9793	3420	6942
Belt; W/50" Belt O.C. ....	9127	3500	6950
<b>VG-2</b>			
Belt .....	9127	3500	6950
<b>VG-20</b>			
Belt .....	9649		3V315
<b>WP-2A</b>			
Belt .....	9852	2200	6820
<b>WESTERN AUTO</b>			
<b>2X2603; 2X2703; 2X2903</b>			
Belt .....	100140	2170	6817
<b>2X6414</b>			
Belt .....	7540935	2310	6831
<b>2X6434</b>			
Traction .....	7540239	2290	6829
<b>2XC3240; 2XC3442</b>			
Belt .....	7540239	2290	6829
<b>2XC3538</b>			
Blade .....	7540109		6843
Trans. ....	7540104		6832
<b>2XC3539</b>			
Belt .....	7540109		6843
<b>2XC3624; 2XC3634</b>			
Traction .....	7540242	2320	6832
<b>2XC3637</b>			
Traction .....	7540114	2240	6824



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>2XC3715</b>			
Belt; W/42" Belt O.C. ....	7540116	2420	6842
Belt; W/43" Belt O.C. ....	7540109		6843
<b>2XC3716</b>			
Belt .....	7540109		6843
<b>2XC3717</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>2XC3724</b>			
Traction .....	7540242	2320	6832
<b>2XC3737</b>			
Traction .....	7540114	2240	6824
<b>2XC3833</b>			
Drive .....	7540126		6820
<b>2XC4234</b>			
Blade .....	7540935	2310	6831
Drive .....	7540242	2320	6832
<b>2XC4334</b>			
Belt .....	7540935	2310	6831
<b>2XC4429</b>			
Blade .....	7540141		6183
<b>2XC4434; 2XC4444</b>			
Traction .....	7540114	2240	6824
<b>2XC4448</b>			
Drive .....	7540126		6820
<b>2XC4522</b>			
Belt .....	7540109		6843
<b>2XC4524</b>			
Drive .....	7540121		6831
<b>2XC4534</b>			
Blade .....	7540144	3550	6955
Traction .....	7540143		6728
<b>2XC6324</b>			
Belt .....	7540935	2310	6831
<b>2XC6334; 2XC6344; 2XC6345</b>			
Traction .....	7540114	2240	6824
<b>2XC6414</b>			
Belt .....	7540935	2310	6831
<b>2XC6434</b>			
Traction .....	7540239	2290	6829
<b>2XC6522</b>			
Belt .....	7540109		6843
<b>2XC6524; 2XC6534</b>			
Blade; W/43" Belt O.C. ....	7540109		6843
Blade; W/55" Belt O.C. ....	7540144	3550	6955
Drive; W/28" Belt O.C. ....	7540143		6728
Drive; W/31" Belt O.C. ....	7540121		6831
Drive; W/32" Belt O.C. ....	7540177		6832
<b>93-6334-2; 93-6354-0</b>			
Traction .....	7540114	2240	6824
<b>93-6524-8</b>			
Blade .....	7540109		6843
Trans. ....	7540177		6832
<b>93-6614-7</b>			
Drive .....	7540219	2260	6826
<b>93-6624-6</b>			
Drive; W/28" Belt O.C. ....	7540163		6828
Drive; W/31" Belt O.C. ....	7540935	2310	6831
<b>118-530</b>			
Belt .....	7540109		6843
<b>123-270; 123-280; 123-290</b>			
Traction .....	7540114	2240	6824

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>123-550</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>123-690</b>			
Traction .....	7540239	2290	6829
<b>128-220</b>			
Traction .....	7540242	2320	6832
<b>128-550</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>7109B88</b>			
Blade .....	7540326		6862
Traction .....	7540327		6828
<b>MTD414A88</b>			
Blade .....	7540328		6949
Traction .....	7540344		6873
<b>MTD3944A98; MTD3944B98</b>			
Traction .....	7540343		6731
<b>MTD4114A68</b>			
Traction .....	7540104		6832
<b>MTD4146A68</b>			
Blade .....	7540326		6862
Traction .....	7540327		6828
<b>MTD4146A78</b>			
Blade .....	7540327		6928
<b>MTD4234</b>			
Traction .....	7540242	2320	6832
<b>MTD4334</b>			
Belt .....	7540935	2310	6831
<b>MTD4434</b>			
Traction .....	7540114	2240	6824
<b>MTD4522</b>			
Belt .....	7540109		6843
<b>MTD4524</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>MTD4534</b>			
Blade .....	7540144	3550	6955
Traction .....	7540143		6728
<b>MTD6334; MTD6344</b>			
Traction .....	7540114	2240	6824
<b>MTD6414A37</b>			
Belt .....	7540935	2310	6831
<b>MTD6434A37</b>			
Traction .....	7540239	2290	6829
<b>MTD6522</b>			
Belt .....	7540109		6843
<b>MTD6524A08</b>			
Blade .....	7540109		6843
Trans. ....	7540177		6832
<b>MTD6524A37; MTD6524A47</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>MTD6524A57; MTD6524A77</b>			
Blade .....	7540109		6843
Trans. ....	7540177		6832
<b>MTD6534</b>			
Blade .....	7540144	3550	6955
Traction .....	7540143		6728
<b>MTD6624</b>			
Belt .....	7540935	2310	6831
<b>MTD7109A88; MTD7109B88</b>			
Blade .....	7540151		6967

# WALK BEHIND MOWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>MTD7115A88</b>			
Blade .....	7540329		6630BR
<b>MTD7129A88</b>			
Blade .....	7540349		6637BR
Deck .....	7540350		6464BR
Eng. To J.S. ....	7540245		6859
J.S. To Trans. ....	7540244		6840
<b>WHEEL HORSE</b>			
<b>2-5000</b>			
Traction .....	104290	1293	
<b>WHEELER</b>			
<b>WHW-22CD</b>			
Blade .....	170647		6844
<b>WHITE OUTDOOR PRODUCTS</b>			
<b>118R; 123-898C</b>			
Drive .....	7540343		6731
<b>124-294</b>			
Belt .....	7540114	2240	6824
<b>124-364; 124-374</b>			
Traction .....	7540252		6833
<b>124-574</b>			
Blade .....	7540267		6859
<b>148N; 166B</b>			
Drive .....	7540343		6731
<b>202; 204</b>			
Drive .....	7540104		6832
<b>365; 366; 367</b>			
Drive .....	7540292		6826
<b>476B; 476R; 488N</b>			
Drive .....	7540346		6411BR
<b>560B</b>			
Drive; W/28" Belt O.C. ....	7540327		6928
Drive; W/62" Belt O.C. ....	7540326		6862
<b>573; 574</b>			
Blade; W/28" Belt O.C. ....	7540143		6728
Blade; W/59" Belt O.C. ....	7540267		6859
<b>795; 797</b>			
Belt; W/26" Deck .....	7540264		6639BR
<b>826-B; 826-E; 826-R; 828R; 848E; 848R; 898N</b>			
Drive .....	7540343		6731
<b>990-005; 990-142</b>			
Drive .....	7540935	2310	6831
<b>990-145</b>			
Drive; W/28" Belt O.C. ....	7540163		6828
Drive; W/31" Belt O.C. ....	7540935	2310	6831
<b>991-142</b>			
Drive .....	7540935	2310	6831
<b>991-145</b>			
Drive .....	7540163		6828
<b>991-246</b>			
Belt .....	7540114	2240	6824
<b>991-247</b>			
Blade .....	7540144	3550	6955
Trans. ....	7540143		6728
<b>991-260</b>			
Belt .....	7540252		6833
<b>994-371</b>			
Belt .....	7540114	2240	6824
<b>994-372; 994-373</b>			
Belt .....	7540252		6833
<b>994-374</b>			
Blade .....	7540267		6859

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE OUTDOOR PRODUCTS - Continued</b>			
<b>E8980</b>			
Drive .....	7540343		6731
<b>WHITE STORES</b>			
<b>86-305; 87-305</b>			
Drive .....	7540114	2240	6824
<b>87-308</b>			
Blade .....	7540116	2420	6842
<b>87-311</b>			
Blade .....	7540109		6843
Traction; W/31" Belt O.C. ....	7540121		6831
Traction; W/32" Belt O.C. ....	7540177		6832
<b>87-312</b>			
Blade .....	7540109		6843
Traction .....	7540177		6832
<b>87-757; 87-760</b>			
Drive .....	7540114	2240	6824
<b>87-765</b>			
Drive .....	7540163		6828
<b>87-767</b>			
Drive .....	7540935	2310	6831
<b>87-770</b>			
Blade .....	7540109		6843
Traction .....	7540177		6832
<b>87-7125</b>			
Drive .....	7540114	2240	6824
<b>87-7234</b>			
Drive .....	7540242	2320	6832
<b>87-7248</b>			
Belt .....	7540252		6833
<b>110-500</b>			
Blade .....	7540116	2420	6842
<b>110-530</b>			
Blade .....	7540109		6843
<b>112-500; 113-500-02; 114-500</b>			
Blade .....	7540116	2420	6842
<b>115-500</b>			
Blade .....	7540109		6843
<b>120-270</b>			
Drive .....	7540114	2240	6824
<b>120-320</b>			
Drive .....	7540242	2320	6832
<b>120-550</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>120-570</b>			
Blade .....	7540144	3550	6955
Traction .....	7540143		6728
<b>122-290</b>			
Drive .....	7540114	2240	6824
<b>122-550</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>123-220</b>			
Drive .....	7540242	2320	6832
<b>123-290</b>			
Drive .....	7540114	2240	6824
<b>123-550</b>			
Blade .....	7540109		6843
Traction .....	7540121		6831
<b>124-290; 124-294</b>			
Drive .....	7540114	2240	6824
<b>124-550</b>			
Blade .....	7540109		6843





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE STORES - Continued</b>			
<b>124-550 - Continued</b>			
Traction .....	7540121		6831
<b>125-550</b>			
Blade .....	7540109		6843
Traction .....	7540104		6832
<b>153-518</b>			
Drive .....	7540126		6820
<b>WORLDLAWN POWER EQUIPMENT</b>			
<b>WY28B11BS</b>			
Traction .....	SA-34		6835
Wheel Drive .....	2800004		6835
<b>WY28B11BSE; WY28B11HD; WY28B11HDE</b>			
Eng. To Deck .....	2800015		6858
Wheel Drive .....	2800004		6835
<b>WY28T11BSE; WY28T11HD; WY28T11HDE</b>			
Eng. To Deck .....	2832003		6896BR
Wheel Drive .....	3200002		6839
<b>WY36FS481VH</b>			
Deck Drive .....	363210		6573BR
Trans. ....	363212		7025BR
<b>WY48FS481V</b>			
Blade - Left .....	483030		6614BR
Blade - Right .....	483031		6864BR
Trans. ....	363212		7025BR
Wheel Drive .....	363312		②6809BR
<b>WY48FS481VH</b>			
Blade - Left .....	483030		6614BR
Blade - Right .....	483031		6864BR
Trans. ....	363212		7025BR
<b>WY2811BS; WY2811BSE; WY2811HD; WY2811HDE</b>			
Eng. To Deck .....	2800015		6858
Wheel Drive .....	2800004		6835
<b>WY3211BS; WY3211BSE; WY3211HD; WY3211HDE; WY3213BS; WY3213BSE; WY3213HD; WY3213HDE; WY3216KW; WY3216KWE</b>			
Wheel Drive .....	3200002		6839
<b>WY3613HD; WY3613HDE; WY3616KW; WY3616KWE</b>			
Deck Drive .....	3602003		6555BR
Wheel Drive .....	3600002		7037BR
<b>WRIGHT MANUFACTURING, INC.</b>			
<b>WV3215B; WV3215KAW; WV3215KOH</b>			
Deck Drive; Ser. No. 28215 & After .....	71460003		6815BR
Hydro.; Ser. No. 28214 & Before .....	71460041		6685BR
Hydro.; Ser. No. 28215 & After .....	71460066		6820BR
<b>WV3615KAW; WV3617KAW; WV3617KAWRE</b>			
Deck Drive; Ser. No. 28214 & Before .....	71460043		6839BR
Deck Drive; Ser. No. 28215 & After .....	71460013		6839BR
Hydro.; Ser. No. 28214 & Before .....	71460041		6685BR
Hydro.; Ser. No. 28215 & After .....	71460066		6820BR
<b>WV4815KAW; WV4817KAW; WV4817KAWRE; WV4819KAW</b>			
Blade Drive; Ser. No. 28215 & After .....	71460070		6822BR
Eng. To Deck; Ser. No. 28214 & Before ..	71460043		6839BR
Eng. To Deck; Ser. No. 28215 & After .....	71460013		6839BR
Hydro.; Ser. No. 28214 & Before .....	71460041		6685BR
Hydro.; Ser. No. 28215 & After .....	71460066		6820BR
<b>WV5217KAW; WV5217KAWRE; WV5219KAW</b>			
Blade Drive; Ser. No. 28214 & Before .....	71460002		6564BR
Blade Drive; Ser. No. 28215 & After .....	71460065		6823BR
Eng. To Deck; Ser. No. 28214 & Before ..	71460043		6839BR
Eng. To Deck; Ser. No. 28215 & After .....	71460071		6856BR
Hydro.; Ser. No. 28214 & Before .....	71460041		6685BR
Hydro.; Ser. No. 28215 & After .....	71460066		6820BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WRIGHT MANUFACTURING, INC. - Continued</b>			
<b>WVG3215KAW; WVG3216KAW</b>			
Deck Drive .....	71460107		6866BR
Eng. ....	71460095		A40
Wheel Drive .....	71460087		6440BR
<b>WVG3615KAW; WVG3616KAW</b>			
Deck Drive .....	71460013		6839BR
Eng. ....	71460095		A40
Wheel Drive .....	71460087		6440BR
<b>WVG4815KAW; WVG4816KAW; WVG4817KAW</b>			
Blade Drive .....	71460070		6822BR
Eng. ....	71460095		A40
Eng. To Deck .....	71460013		6839BR
Wheel Drive .....	71460087		6440BR
<b>WVH3216KAW</b>			
Deck Drive .....	71460003		6815BR
Hydro. ....	71460066		6820BR
<b>WVH3616KAW; WVH3618KAWRE</b>			
Deck Drive .....	71460013		6839BR
Hydro. ....	71460066		6820BR
<b>WVH4818KAWRE</b>			
Blade Drive .....	71460070		6822BR
Eng. To Deck .....	71460013		6839BR
Hydro. ....	71460066		6820BR
<b>WVH5218KAWRE; WVH5220KAWRE</b>			
Blade Drive .....	71460065		6823BR
Eng. To Deck .....	71460071		6856BR
Hydro. ....	71460066		6820BR
<b>WVP3215KAW</b>			
Deck Drive .....	71460003		6815BR
Hydro. ....	71460066		6820BR
<b>WVP3615KAW; WVP3617KAW; WVP3617KAWRE</b>			
Deck Drive .....	71460013		6839BR
Hydro. ....	71460066		6820BR
<b>WVP4815KAW; WVP4817KAW; WVP4817KAWRE; WVP4819KAW</b>			
Blade Drive .....	71460070		6822BR
Eng. To Deck .....	71460013		6839BR
Hydro. ....	71460066		6820BR
<b>WVP5217KAWRE; WVP5219KAWRE</b>			
Blade Drive .....	71460065		6823BR
Eng. To Deck .....	71460071		6856BR
Hydro. ....	71460066		6820BR
<b>YARD HOGG</b>			
<b>High Wheel</b>			
Eng. To Deck .....			6953
J.S. To J.S. ....			6829
<b>YARD MACHINES</b>			
<b>12A-138C</b>			
Drive .....	7540343		6731
<b>12A-260A; 12A-264A</b>			
Drive .....	7540466		6737
<b>12A-288C</b>			
Drive .....	7540484		6739
<b>12A-378N; 12A-379B</b>			
Drive .....	7540271		6557BR
<b>12A-455G</b>			
Drive .....	7540465		6736
<b>12A-458B</b>			
Drive .....	7540271		6557BR
<b>12A-468N</b>			
Drive .....	7540465		6736

Lawn & Garden Equipment

②Two Required

**WALK BEHIND MOWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD MACHINES - Continued</b>			
12A-528N			
Drive .....	7540369		6426BR
12A-529B			
Drive .....	7540483		6738
12A-568N			
Drive .....	7540465		6736
12A-588N			
Drive .....	7540466		6737
<b>YARD-MAN</b>			
44"			
Eng. To Left Blade; W/16 H.P. Eng. ....	7540230		6755BR
46"			
Blade - Left To Right; W/16 H.P. Eng. ....	7540293		6501BR
121-118R			
Drive .....	7540343		6731
121-638R			
Drive .....	7540327		6928
121-898B; 121-898F; 121-898R; 121C898B; 121C898E; 121C898R			
Drive .....	7540343		6731
1300-1			
Eng. To J.S. ....	165120		6818
2560-0-6			
Drive .....	7540935		6831
12213			
Drive .....	7540104		6832
12294			
Drive .....	7540114	2240	6824
12304-0; 12304-1; 12304-8; 12304-9; 12306-0; 12306-1; 12344-0			
Drive .....	7540935		6831
12344-1			
Drive .....	7540252	2330	6833
12346-0			
Drive .....	7540935		6831
12346-1			
Drive .....	7540252	2330	6833
12351-0; 12351-1; 12351-8; 12351-9; 12352; 12355; 12357			
Drive .....	7540935		6831
12365			
Drive .....	7540292		6826
12374; 12376			
Drive .....	7540252	2330	6833
12550-0; 12550-1			
Blade .....	7540109		6843
Drive .....	7540177		6832
12553			
Belt; W/33" Belt O.C. ....	7540146		6833
Belt; W/44" Belt O.C. ....	7540274		6844
12554			
Belt; W/33" Belt O.C. ....	7540146		6833
Belt; W/44" Belt O.C. ....	7540222		6844
12560			
Blade; W/5 H.P. Eng. ....	7540326		6862
Traction; W/5 H.P. Eng. ....	7540327		6928
12570; 12570-0; 12570-1			
Blade .....	7540144	3550	6955
Drive .....	7540143		6728
12574			
Belt; W/28" Belt O.C. ....	7540143		6728
Belt; W/59" Belt O.C. ....	7540267		6859

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD-MAN - Continued</b>			
12871; 12872; 12884; 12886			
Drive .....	7540343		6731
15585; 15590			
Drive .....	165120		6818
21031			
Drive .....	7540216		6729
21430			
Drive .....	7540325		6857
21700			
Drive .....	7540190		6839
24596; 24604			
Drive .....	7540142		6673BR
31183; 31184; 31193			
Drive .....	7540101		6517BR
31340			
Drive .....	7540256		6729
High Wheeler 26"			
Blade; W/5 H.P. Eng. ....	7540326		6862
<b>YAZOO</b>			
A-33-22			
Blade; W/Clinton Eng.; 1970 & Newer ....	205041	2490	
Blade; W/Wisconsin Eng.; 1970 & Newer	205039	2390	6839
Friction Drive; W/26" Belt O.C.; 1970 & Newer	205426		6826
Friction Drive; W/42" Belt O.C.; 1970 & Newer	205142		6842
AV20; AV20-FSP			
Blade .....	205039	2390	6839
Friction Drive .....	205425		6825
AV22-FSP			
Blade .....	205041	2490	
Friction Drive .....	205426		6826
B-3			
Blade; 1970 & Newer .....	205144		6844
B-6			
Blade; W/B. & S. Eng. ....	205042		6842
Blade; W/Wisconsin Eng. ....	205144		6844
B24			
Blade .....	205044	2440	6844
B-33			
Blade; 1970 & Newer .....	205144		6844
Friction Drive .....	205426		6826
B33-24FSP; B33-24SP			
Belt; W/26" Belt O.C. ....	205426		6826
Belt; W/28" Belt O.C. ....	205028	2280	6828
Belt; W/44" Belt O.C. ....	205144		6844
Belt; W/45" Belt O.C. ....	205045		6845
Belt; W/58" Belt O.C. ....	205058	2580	6858
B-66			
Blade; W/B. & S. Eng. ....	205042		6842
Friction Drive .....	205425		6825
H-66-26			
Blade .....	205144		6844
Friction Drive .....	205429		6829
Harry S-22			
Traction .....	205049	2490	
P20			
Blade; W/39" Belt O.C. ....	205039	2390	
Blade; W/45" Belt O.C. ....	205045		6845
Traction .....	205425		6825
P22; P24			
Blade; W/44" Belt O.C. ....	205144		6844
Blade; W/45" Belt O.C. ....	205045		6845
Traction .....	205425		6825

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YAZOO - Continued</b>			
<b>PTO</b>			
Belt .....	205137		6940
<b>PTOB; PTOW</b>			
Trans.; W/Wisconsin Eng. ....	205074		6976
<b>S20</b>			
Blade; W/39" Belt O.C. ....	205039	②2390	
Blade; W/44" Belt O.C. ....	205044	2440	6844
Blade; W/45" Belt O.C. ....	205045		6845
Traction .....	205425		6825
<b>S22</b>			
Blade .....	205512		6843
Traction .....	205425		6825
<b>S24</b>			
Blade .....	205042		6842
Traction .....	205425		6825
<b>S26</b>			
Blade .....	205147	②2470	
<b>W36</b>			
Traction .....	205333		3V335
<b>YAZOO/KEES</b>			
<b>KHKW36140; KHKW36151</b>			
Deck .....	101959		6812BR
<b>KHKW48170; KHKW48171</b>			
Primary .....	101958		6814BR
<b>KKFW48180</b>			
Deck .....	103240		6787BR
<b>KKFW52180; KKFW52210</b>			
Deck .....	107095		7069BR
<b>KKH36132</b>			
Deck .....	101959		6812BR
Drive .....	101956		6813BR
<b>KKW32121; KKW32132</b>			
Deck .....	102148		6573BR
<b>KKW36121; KKW36132; KKW36141</b>			
Deck .....	101959		6812BR
Drive .....	101956		6813BR
<b>KKW48141; KKW48151; KKW48152</b>			
Drive .....	101956		6813BR
Primary .....	101958		6814BR

②Two Required

Manufacturers' Part Number Shown for Reference Only

Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS</b>			
<b>5015 Compact</b> Snow Thrower Attachment; W/52" Auger .....	2087759		6866
<b>5020 Compact; 5030 Compact</b> Fan .....	2097654	9400	9400HD
<b>5220</b> Fan & Alt. ....		9380	9380HD
<b>ARMSTRONG TRACTOR CO.</b>			
<b>1872; 2070; 2072</b> Deck .....			6956
<b>2174</b> Hyd. Pump .....	6949	2400	
<b>BOLENS</b>			
<b>G152 Compact; G154 Compact; G174 Compact</b> Fan & Alt. ....	1873737	7350	
<b>G192 Compact; G194 Compact</b> Fan & Alt. ....	1876225	9385	9385HD
<b>G242 Compact; G244 Compact</b> Fan & Alt. ....	1876226	9385	9385HD
<b>CASE, J.I.</b>			
<b>DX35</b> Fan & Alt. ....	301525A1	9370	9370HD
<b>DX40; DX45</b> Fan .....	301525A1	9370	9370HD
<b>CUB CADET</b>			
<b>5264 Compact</b> Fan .....	BS-821075	7370	
<b>7232 Compact; 7233 Compact; 7234 Compact; 7235 Compact</b> Fan & Alt. ....	REMF1360	7360	
<b>FORD</b>			
<b>1100 Compact; 1110 Compact</b> Fan & Alt. ....	13321	7320	
<b>1210 Compact</b> Fan & Alt. ....	REMF1315	7315	
<b>1300 Compact</b> Fan & Alt. ....	13321	7320	
<b>1310 Compact</b> Fan & Alt. ....	13311	7312	
<b>1320 Compact</b> Fan & Alt. ....	SBA080109024	9380	9380HD
<b>1500 Compact</b> Fan & Alt. ....		9440	9440HD
<b>1510 Compact</b> Fan & Alt.; W/35 1/8" Belt O.C. .... Fan & Alt.; W/51" Belt O.C. ....	REMF1350 REMF1510	7350 7512	
<b>1520 Compact</b> Fan & Alt. ....	SBA080109024	9380	9380HD
<b>1600 Compact; 1700 Compact</b> Fan & Alt. ....		9440	9440HD
<b>1710 Compact</b> Fan & Alt.; W/35 1/8" Belt O.C. .... Fan & Alt.; W/51" Belt O.C. ....	REMF1350 REMF1510	7350 7512	
<b>1720 Compact</b> Fan & Alt.; W/37 3/4" Belt O.C. .... Fan & Alt.; W/38" Belt O.C. ....		9375 9380	9375HD 9380HD
<b>1900 Compact; 1910 Compact</b> Fan & Alt. ....		9440	9440HD

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FORD - Continued</b>			
<b>1920 Compact</b> Fan & Alt.; W/37 1/2" Belt O.C. .... Fan & Alt.; W/44 1/4" Belt O.C. ....		9375 9440	9375HD 9440HD
<b>2120 Compact</b> Fan & Alt. ....			AX42
<b>INTERNATIONAL</b>			
<b>235; 254</b> Fan & Alt. ....	MD007528	7370	
<b>284 Diesel</b> Fan & Alt. ....	197810984	9390	9390HD
<b>JOHN DEERE</b>			
<b>324 Compact</b> Forward .....	M81036		6833
Reverse .....	M81035	2330	6833
<b>624 Compact</b> Forward .....	M81036		6833
Reverse .....	M81037		6832
<b>650 Compact</b> Fan & Gen. ....	CH15509	9360	9360HD
<b>655 Compact</b> Fan & Alt. ....	M800313	7345	
<b>750 Compact</b> Fan & Alt. .... Fan & Gen. ....		9365 9360	9365HD 9360HD
<b>755 Compact; 756 Compact</b> Fan & Alt. ....	M800313	7345	
<b>770 Compact</b> Fan & Alt.; W/35 5/8" Belt O.C. .... Fan & Alt.; W/41 3/8" Belt O.C. ....	M800313 M802627	7345 9412	9412HD
<b>820 Compact; 820A Compact</b> Drive; W/Rear Tine Tiller .....	PT7513		6722
<b>850 Compact</b> Fan & Alt.; Ser. No. 007760 & Before .... Fan & Alt.; Ser. No. 007761 & After .....		9375 9400	9375HD 9400HD
Fan & Alt.; Ser. No. 016000 & Before .... Fan & Alt.; Ser. No. 016001 & After .....		9375 9400	9375HD 9400HD
<b>855 Compact; 856 Compact</b> Fan & Alt. ....	M805441	9385	9385HD
<b>870 Compact</b> Fan & Alt. ....		9412	9412HD
<b>900HC Compact</b> Fan & Alt. ....	CH14022	9400	9400HD
<b>950 Compact</b> Fan & Alt.; Ser. No. 018059 & Before .... Fan & Alt.; Ser. No. 018060 & After .....	CH10367 CH12865	9380 9412	9380HD 9412HD
Fan & Alt.; Ser. No. 020000 & Before .... Fan & Alt.; Ser. No. 020001 & After .....	CH12865	9380 9412	9380HD 9412HD
<b>955 Compact</b> Fan & Alt. ....	M805011	9375	9375HD
<b>970 Compact</b> Fan & Alt. .... Primary .....		9412	9412HD 6860
Secondary .....	M82734 M82462		6743BR
<b>1050 Compact; 1051 Compact</b> Fan & Alt.; W/41 1/4" Belt O.C. .... Fan & Alt.; W/49 1/4" Belt O.C. ....	CH12865 REMF6480	9412 9490	9412HD 9490HD
<b>1070 Compact</b> Fan & Alt. ....	M802627	9412	9412HD
<b>1250 Compact; 1450 Compact; 1650 Compact</b> Fan .....	CH16856	9465	9465HD



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>2210 Compact</b>			
Fan .....	M811285	7370	
<b>2305 Compact</b>			
Fan .....	MIU800108	9370	9370HD
<b>2320 Compact</b>			
Fan .....	M805441	9385	9385HD
<b>2520 Compact</b>			
Fan .....	M801821	9390	9390HD
<b>3005 Compact</b>			
Fan .....	M801821	9390	9390HD
W.P. ....	M801821	9390	9390HD
<b>3032E Compact</b>			
Fan .....	M801821	9390	9390HD
<b>3033R Compact</b>			
Deck Drive; W/60" Deck .....	M136137		6567BR
<b>3038E Compact</b>			
Fan .....	M801821	9390	9390HD
<b>3039R Compact; 3046R Compact</b>			
Deck Drive; W/60" Deck .....	M136137		6567BR
<b>3120 Compact; 3203 Compact; 3320 Compact</b>			
Fan .....	LVU11661	9415	9415HD
<b>3520 Compact; 3720 Compact</b>			
A.C. ....	MIU10141	9505	9505HD
Fan .....	LVU11661	9415	9415HD
<b>4010 Compact</b>			
Fan; 2004 & Older .....	R41681	9560	9560HD
Fan; 2005 & Newer; W/36 1/2" Belt			
O.C. ....	M800347	7360	
Fan; 2005 & Newer; W/36" Belt O.C. ....	M802674	7360	
Fan; 2005 & Newer; W/37" Belt O.C. ....	M811285	7370	
<b>4100 Compact</b>			
Fan .....	M802674	7360	
Fan & Alt. ....	M802674	7360	
<b>4105 Compact</b>			
Fan .....	LVU11835	9405	9405HD
<b>4120 Compact</b>			
Fan & Alt. ....	R515222	K060935	
<b>4200 Compact</b>			
Fan .....		9390	9390HD
<b>4300 Compact</b>			
Fan .....	M808685	9412	9412HD
<b>4320 Compact</b>			
Fan & Alt. ....	R515222	K060935	
<b>4400 Compact</b>			
Fan .....	M808685	9412	9412HD
<b>4500 Compact</b>			
Fan; W/40" Belt O.C. ....	M802627	9412	9412HD
Fan; W/41 1/2" Belt O.C. ....	M809527	9425	9425HD
<b>4520 Compact</b>			
A.C. ....	R71603	9415	9415HD
Fan & Alt. ....	AR43219	Ⓣ9600	Ⓣ9600HD
<b>4600 Compact</b>			
Fan; W/40" Belt O.C. ....	M802627	9412	9412HD
Fan; W/41 1/2" Belt O.C. ....	M809527	9425	9425HD
<b>4700 Compact</b>			
Fan .....	M809527	9425	9425HD
<b>4720 Compact</b>			
Fan, Alt. & A.C. ....	R515222	K060935	
<b>5200 Compact; 5300 Compact; 5400 Compact</b>			
A.C. ....	R128502	9630	9630HD
Fan .....	R73784		TR22525
<b>5500 Compact</b>			
A.C. ....	R128502	9630	9630HD
Fan; W/Cab .....	E75596		TR22553

ⓉTwo Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>5500 Compact - Continued</b>			
Fan; W/O Cab .....	N150864		TR22545
<b>KUBOTA</b>			
<b>1345DT</b>			
Fan & Alt.; W/D1310A, V1501A Eng. ....		7420	
<b>B1550 Compact</b>			
Blade Drive; W/48" Deck .....	70080-01245		6998
Fan & Alt.; W/D950 Diesel Eng. ....	70000-73783	7360	
<b>B2320 Compact; B2620 Compact</b>			
Blade Drive; W/54" Deck .....	K5351-34710		6796BR
Blade Drive; W/60" Deck .....	K5763-34712		7103BR
Fan & W.P. ....	16241-97010	7370	
<b>B2630 Compact</b>			
Alt. ....	16241-97010	7370	
Blade Drive; W/60" Deck .....	K5763-34710		7103BR
Blade Drive; W/72" Deck .....	K5671-34710		7104BR
<b>B2920 Compact</b>			
Blade Drive; W/54" Deck .....	K5351-34710		6796BR
Blade Drive; W/60" Deck .....	K5763-34712		7103BR
Fan .....	16241-97010	7370	
<b>B3000 Compact</b>			
Alt. ....	16241-97010	7370	
Blade Drive; W/60" Deck .....	K5763-34710		7103BR
Blade Drive; W/72" Deck .....	K5671-34710		7104BR
<b>B3030 Compact</b>			
Alt. ....	16241-97010	7370	
Blade Drive; W/60" Deck .....	K5763-34710		7103BR
Blade Drive; W/72" Deck .....	K5671-34710		7104BR
<b>B4200 Compact</b>			
Blade Drive; W/48" Deck .....	70080-01245		6998
Fan; W/D6550A, D750A, Z500A, 71600 Eng. ....	70000-73818	7300	
<b>B5100 Compact</b>			
Fan; W/D6550A, D750A, Z500A, 71600 Eng. ....	70000-73818	7300	
<b>B5100E Compact</b>			
Fan; W/D6550A, D750A, Z500A, 71600 Eng. ....	1523172530	7300	
<b>B5200 Compact</b>			
Blade Drive; W/48" Deck .....	70080-01245		6998
Fan & Alt.; W/D950 Diesel Eng. ....	70000-73783	7360	
<b>B6000 Compact</b>			
Fan; W/D6550A, D750A, Z500A, 71600 Eng. ....	70000-73818	7300	
<b>B6100 Compact</b>			
Fan; W/D6550A, D750A, Z500A, 71600 Eng. ....	70000-73783	7360	
<b>B6100E Compact</b>			
Fan; W/D6550A, D750A, Z500A, 71600 Eng. ....	1523172530	7300	
<b>B6200 Compact</b>			
Blade Drive; W/60" Deck .....	70725-34710		B117
Fan & Alt.; W/D950 Diesel Eng. ....	70000-73783	7360	
P.T.O.; W/48" Deck .....	70722-32430		6941
<b>B7000 Compact</b>			
Fan; W/D6550A, D750A, Z500A, 71600 Eng. ....	1523172530	7300	
<b>B7100 Compact</b>			
Fan; W/D6550A, D750A, Z500A, 71600 Eng. ....	70000-73818	7300	
<b>B7200 Compact</b>			
Fan & Alt.; W/D950 Diesel Eng. ....	70000-73783	7360	
<b>B7800 Compact</b>			
Blade Drive; W/60" Deck .....	K5763-34710		7103BR
Blade Drive; W/72" Deck .....	K5671-34710		7104BR
Fan .....	16241-97010	7370	

Lawn & Garden Equipment



# COMPACT TRACTORS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>KUBOTA - Continued</b>			
<b>B8200 Compact</b>			<b>B108</b>
Blade Drive; W/60" Deck .....	70722-34710		
Fan & Alt.; W/D950 Diesel Eng. ....	70000-73783	<b>7360</b>	
<b>B9200 Compact</b>			
Fan & Alt.; W/D950 Diesel Eng. ....	70000-73783	<b>7360</b>	
<b>BX24 Compact</b>			
Alt. ....		<b>7350</b>	
Blade Drive; W/54" Deck .....	K5351-34710		<b>6796BR</b>
Blade Drive; W/60" Deck .....	K5763-34712		<b>7103BR</b>
Fan .....	16883-97010	<b>7350</b>	
<b>BX25</b>			
Blade Drive; W/54" Deck .....	K5351-34710		<b>6796BR</b>
Blade Drive; W/60" Deck .....	K5763-34712		<b>7103BR</b>
Fan .....	16883-97010	<b>7350</b>	
<b>BX1800 Compact</b>			
Blade Drive; W/54" Deck .....	K5351-34710		<b>6796BR</b>
Blade Drive; W/60" Deck .....	K5763-34710		<b>7103BR</b>
Fan .....	15881-97010	<b>7345</b>	
<b>BX1850 Compact</b>			
Blade Drive; W/54" Deck .....	K5351-34710		<b>6796BR</b>
Fan .....	15881-97010	<b>7345</b>	
<b>BX1860 Compact</b>			
Blade Drive; W/48" Deck .....	K5700-34712		<b>7102BR</b>
Blade Drive; W/54" Deck .....	K5351-34710		<b>6796BR</b>
Fan .....	15881-97010	<b>7345</b>	
<b>BX2350 Compact</b>			
Blade Drive .....	K5221-71410		<b>6980BR</b>
Fan .....	16883-97010	<b>7350</b>	
<b>BX2360 Compact</b>			
Blade Drive; W/54" Deck .....	K5351-34710		<b>6796BR</b>
Blade Drive; W/60" Deck .....	K5763-34712		<b>7103BR</b>
Fan .....	16883-97010	<b>7350</b>	
<b>BX2660</b>			
Blade Drive; W/54" Deck .....	K5351-34710		<b>6796BR</b>
Blade Drive; W/60" Deck .....	K5763-34712		<b>7103BR</b>
Fan .....	16241-97010	<b>7370</b>	
<b>D850-BWS</b>			
Fan & Alt.; W/18 H.P. Eng. ....	FM355	<b>7355</b>	
<b>D1402</b>			
Fan & Alt.; W/D1310A, V1501A Eng.;			
W/28.5 H.P. Eng. ....		<b>7420</b>	
<b>G2460</b>			
Blade Drive; W/54" Deck .....	K5351-34710		<b>6796BR</b>
Blade Drive; W/60" Deck .....	K5763-34710		<b>7103BR</b>
Fan .....	15881-97010	<b>7345</b>	
<b>G3200; G4200; G4200H</b>			
Blade Drive; W/40" Deck .....	70713-34770		<b>6984</b>
Blade Drive; W/44" Deck .....	70712-34710		<b>6989</b>
Fan & Alt. ....	15841-97010	<b>7320</b>	
<b>G5200; G5200H</b>			
Blade Drive; W/40" Deck .....	70713-34770		<b>6984</b>
Blade Drive; W/44" Deck .....	70712-34710		<b>6989</b>
Blade Drive; W/48" Deck .....	76500-34710		<b>B94</b>
Fan & Alt. ....	15841-97010	<b>7320</b>	
<b>G6200; G6200H</b>			
Blade Drive; W/40" Deck .....	70713-34770		<b>6984</b>
Blade Drive; W/44" Deck .....	70712-34710		<b>6989</b>
Blade Drive; W/48" Deck .....	76500-34710		<b>B94</b>
Fan & Alt. ....	15881-97010	<b>7345</b>	
<b>L175 Compact; L185 Compact; L185DT Compact</b>			
Fan & Alt. ....	15221-72530	<b>7400</b>	
<b>L200 Compact; L210 Compact</b>			
Fan & Alt. ....	07510-00048	<b>9490</b>	<b>9490HD</b>
<b>L225 Compact</b>			
Fan & Alt. ....	15321-72532	<b>7410</b>	
<b>L225DT Compact</b>			
Fan & Alt. ....	15321-72530	<b>7410</b>	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>KUBOTA - Continued</b>			
<b>L235 Compact</b>			
Fan & Alt.; W/D1310A, V1501A Eng. ....	15401-97010	<b>7417</b>	
<b>L245 Compact</b>			
Fan & Alt.; W/41 5/8" Belt O.C. ....	15321-72530	<b>7410</b>	
<b>L245DT Compact</b>			
Fan & Alt.; W/42 1/8" Belt O.C. ....		<b>7417</b>	
<b>L245H Compact</b>			
Fan & Alt.; W/43 1/8" Belt O.C. ....		<b>7425</b>	
<b>L260 Compact</b>			
Fan & Gen. ....	15601-97010	<b>9440</b>	<b>9440HD</b>
<b>L275DT Compact</b>			
Fan & Alt.; W/D1310A, V1501A Eng. ....	15401-97010	<b>7417</b>	
P.T.O. ....	70722-32430		<b>6941</b>
<b>L285 Compact</b>			
Fan & Alt. ....	15401-97010	<b>7417</b>	
<b>L285DT Compact</b>			
Fan & Alt.; W/D1310A, V1501A Eng. ....	15196-97010	<b>9430</b>	<b>9430HD</b>
<b>L295DT Compact</b>			
Fan & Alt.; W/D1301A Eng. ....	15321-72530	<b>7410</b>	
<b>L305 Compact; L305DT Compact; L345 Compact; L345DT Compact</b>			
Fan & Alt.; W/D1310A, V1501A Eng. ....	15401-97010	<b>7417</b>	
<b>L355S Compact</b>			
Fan & Alt.; W/V1702A Diesel Eng. ....	15469-97010	<b>9425</b>	<b>9425HD</b>
<b>L1302 Compact</b>			
Fan & Alt.; W/D1402 Diesel Eng. ....	REMF1425	<b>7425</b>	
<b>L2050 Compact</b>			
Fan & Alt. ....	17367-97010	<b>7430</b>	
P.T.O. ....	70722-32430		<b>6941</b>
<b>L2250DT Compact; L2550DT Compact</b>			
Fan & Alt. ....	17331-97010	<b>7425</b>	
<b>L3350 Compact</b>			
Fan & Alt. ....	15471-97010	<b>9420</b>	<b>9420HD</b>
<b>L3600 Compact</b>			
Fan & Alt. ....	6415	<b>7417</b>	
<b>L4150 Compact</b>			
Fan & Alt. ....	15196-97010	<b>9430</b>	<b>9730HD</b>
<b>M8030 Compact</b>			
Fan & Alt. ....	REMF1450	<b>②7450</b>	
<b>T1400H</b>			
Blade .....	LB69		<b>6970</b>
Eng. To J.S. ....			<b>6970</b>
J.S. To Blade .....			<b>6968</b>
<b>MAHINDRA</b>			
<b>2415</b>			
Fan .....		<b>7375</b>	
<b>MASSEY FERGUSON</b>			
<b>205-4 Compact</b>			
Fan & Alt. ....		<b>9380</b>	<b>9380HD</b>
<b>210-4 Compact; 220 Compact</b>			
Fan & Alt. ....		<b>9400</b>	<b>9400HD</b>
<b>1010 Compact; 1020 Compact</b>			
Fan & Alt. ....		<b>9380</b>	<b>9380HD</b>
<b>1030 Compact</b>			
Fan & Alt. ....		<b>9451</b>	<b>9451HD</b>
<b>1045 Compact</b>			
Fan & Alt. ....		<b>9430</b>	<b>9430HD</b>
<b>GC2300; GC2310</b>			
Fan .....		<b>7335</b>	

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MITSUBISHI</b>				<b>YANMAR - Continued</b>			
R1500; R2500 Fan & Gen. ....	K7974241	9420	9420HD	<b>YM220 Compact; YM226 Compact</b> Fan & Alt.; W/3T72HA Eng. ....	12102342290	9335	9335HD
<b>NEW HOLLAND</b>				<b>YM240 Compact</b> Fan & Alt.; W/2TR20A Eng. ....	124240	9390	9390HD
Boomer 8N Fan .....	301525A1	9370	9370HD	<b>YM330 Compact</b> Fan & Alt.; W/2Tr20 Eng. ....	124756	9380	9380HD
Boomer 1020; Boomer 1025; Boomer 1030 Fan .....	SBA080109049	7300		W.P.; W/2Tr20 Eng. ....	124240	9390	9390HD
Boomer 2030; Boomer 2035; Boomer 3040; Boomer 3045; Boomer 3050; Boomer 4055; Boomer 4060 Fan .....	301525A1	9370	9370HD	<b>YM336 Compact</b> Fan & Alt.; W/3T72HA Eng. ....		9412	9412HD
T1010; T1030; T1110 Fan .....	SBA080109049	7300					
<b>REFORM</b>							
Metrac 3003 K Fan & Alt. ....	REMF6415	9425	9425HD				
<b>SATOH</b>							
S370 Beaver; S370D Beaver Fan & Alt. ....	KMD011351	7345					
S373 Beaver 3; S470 Buck; S470D Buck Fan & Alt. ....	REMF1370	7370					
S650G Bison Fan & Alt. ....	FM416	7420					
W.P., Gov. & Idler .....	FM41	7417					
S750D Stallion Fan & Alt. ....	913678030	9412	9412HD				
S6300 Bull Fan & Alt. ....		7395					
<b>SIMPLICITY</b>							
9518; 9523; 9528; 2097106; 2097107; 2097150; 2097151; 2097173; 2097185; 2097242 Fan .....	2097654	9400	9400HD				
2097352; 2097353; 2097354; 2097355; 2297353 Fan .....	2097654	9400	9400HD				
<b>YANMAR</b>							
<b>YM135 Compact</b> Fan .....		7290					
Fan & Alt. ....	17291	9290	9290HD				
<b>YM140 Compact; YM140D Compact</b> Fan & Alt. ....	121522	9360	9360HD				
<b>YM146 Compact; YM146D Compact</b> Fan & Alt. ....		9341	9341HD				
<b>YM147 Compact; YM147D Compact</b> Fan & Alt. ....	121522	9360	9360HD				
<b>YM155 Compact; YM155D Compact</b> Fan .....		7290					
Fan & Alt. ....	17291	9290	9290HD				
<b>YM165 Compact; YM165D Compact</b> Fan & Alt. ....	12406442290	9290	9290HD				
<b>YM169 Compact; YM169D Compact</b> Fan & Alt. ....	124064	9290	9290HD				
<b>YM180 Compact; YM180D Compact</b> Fan & Alt. ....	121023	9335	9335HD				
<b>YM186 Compact; YM186D Compact</b> Fan & Alt.; W/3T72HA Eng. ....	12102342290	9335	9335HD				
<b>YM187 Compact; YM187D Compact</b> Eng. To Deck .....	3316808		6732				
Fan & Alt.; W/33 1/2" Belt O.C. ....	121023	9335	9335HD				
Fan & Alt.; W/35" Belt O.C. ....		9350	9350HD				
<b>YM195 Compact</b> Fan & Alt.; W/2TR20A Eng. ....	124240	9390	9390HD				



Manufacturers' Part Number Shown for Reference Only

Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE</b>			
318-100 Drive	7540223		6736
318-450; 318-550 Auger	7540257		6738
Traction	7540256		6729
318-586 Traction	7540256		6729
<b>AIRCAP</b>			
8421 Auger	7540101		6517BR
PJ602/8431; PJ603/8441 Auger	7540367		6390
<b>ALLIS-CHALMERS</b>			
420 Blower, Mfr. No. 1691174	1674312		6837
522 Auger, Mfr. No. 1691412	1674312		6837
Trans., Mfr. No. 1691412	1674308		6390
724 Blower, Mfr. No. 1691143	1666655		6841
Drive, Mfr. No. 1691143	1672732		6731
<b>Sno-Bee</b>			
Blower, W/4 H.P. Eng.; Mfr. No. 2025051	176917		6837
Blower, W/6 H.P. Eng.; Mfr. No. 2025052	1717393		6836
Blower, W/7 H.P. Eng.; Mfr. No. 2025073	161098		6839
Drive, W/4 H.P. Eng.; Mfr. No. 2025051	1665706		6839
Drive, W/6 H.P. Eng.; Mfr. No. 2025052	121216		6838
Drive, W/7 H.P. Eng.; Mfr. No. 2025073	106689		6855
<b>Sno-Pro 21</b>			
Trans.	2026268		6839
<b>Sno-Pro 24; Sno-Pro 28</b>			
Trans.	2029789		6734
<b>Tracker</b>			
Blower, W/4 H.P. Eng.; W/35" Belt O.C.; Mfr. No. 2029954, 2029970	121078		6835
Blower, W/4 H.P. Eng.; W/37" Belt O.C.; Mfr. No. 2029954, 2029970	176917		6837
Blower, W/5 H.P. Eng.; Mfr. No. 1690071, 2029956	161098		6839
Blower, W/6 H.P. Eng.; Mfr. No. 2029955	1717393		6836
Blower, W/7 H.P. Eng.; Mfr. No. 2029971	161098		6839
Drive, W/4 H.P. Eng.; Mfr. No. 2029954, 2029970	1665706		6839
Drive, W/5 H.P. Eng.; Mfr. No. 1690071	1675704		6390
Drive, W/6 H.P. Eng.; Mfr. No. 2029955	1665706		6839
Drive, W/7 H.P. Eng.; W/55" Belt O.C.; Mfr. No. 2029956, 2029971	106689		6855
Drive, W/7 H.P. Eng.; W/61" Belt O.C.; Mfr. No. 2029956, 2029971	1650352		6761
Drive, W/8 H.P. Eng.; Mfr. No. 1600262	1650352		6761
Rotor, W/8 H.P. Eng.; Mfr. No. 1600262	161098		6839
<b>AMERICAN HARDWARE</b>			
Servistar 310-100 Auger	7540223		6736
Servistar 310-600 Auger	7540222		6844
Drive	7540131		6671BR
Servistar 310-800; Servistar 310-860; Servistar 310-960 Auger	7540194		6845
Drive	7540131		6671BR
<b>ARIENS</b>			
10M-L35 Drive	72089		6836

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
10M-L40 Drive	34X89		6836
10M-L55; 10M-L60; 10M-L60D Belt	34X88		3V355
824 Drive	72130		6839
10942; 10954; 10955; 10962; 10965; 10969; 10970; 10975; 10995 Auger	72047		6671BR
22999 Belt	72056		6832
724005 Drive	72083		6376
824005 Blade	72045	3360	
831025; 831032 Belt, W/46" Belt O.C.	072095		6846
Belt, W/50" Belt O.C.	072096		6850
832001 Drive	72110		6871
832002; 832003; 832004 Auger	72114		6583
910002; 910006; 910007; 910008 Belt	72047		6671BR
910009; 910010 Drive	72072		6837
910014 Belt	72047		6671BR
910016; 910018 Drive	72072		6837
910019 Belt	72047		6671BR
910020; 910021 Drive	72072		6837
910942; 910954; 910955; 910962; 910965; 910995 Auger	72047		6671BR
920013; 920021 Auger	07200513		6948BR
920022 Auger	07200513		6948BR
Drive	07200114		6736
920402; 920403 Auger	07200513		6948BR
921023 Auger	07200514		②7009BR
Drive	07200114		6736
921024 Auger	07200514		②7009BR
Drive	07200111		6735
921025 Brush	07238500		7010BR
Drive	07200111		6735
921029 Auger	07200536		②6948BR
921030 Auger	07200514		②7009BR
Drive	07200111		6735
921032; 921037 Auger	07200536		②6948BR

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>921038; 921040</b>			
Auger .....	07200703		Ⓣ6948BR
<b>922002; 922003; 922006; 922008; 922009;</b>			
<b>922010; 922012; 922014; 922016; 922018</b>			
Blower .....	072056	2320	6832
<b>922019; 922020; 922022; 922024; 922025;</b>			
<b>922999</b>			
Blower .....	072056	2320	6832
<b>924013; 924016</b>			
Blower .....	072072		6837
Traction .....	072066		6734
<b>924018; 924020; 924022</b>			
Belt; W/30" Belt O.C. ....	072084		6730
Belt; W/36" Belt O.C. ....	072083		6376
<b>924024</b>			
Blower .....	072108		6376
Traction .....	072066		6734
<b>924025</b>			
Blower .....	072072		6837
Traction .....	072066		6734
<b>924026</b>			
Blower .....	072108		6376
Traction .....	072098		6733
<b>924027</b>			
Blower .....	072072		6837
Traction .....	072098		6733
<b>924028; 924029</b>			
Drive .....	72108		6376
<b>924032</b>			
Blower .....	072108		6376
Traction .....	072098		6733
<b>924033</b>			
Blower .....	72108		6376
Traction .....	72098		6733
<b>924034</b>			
Blower .....	072108		6376
Traction .....	072066		6734
<b>924035</b>			
Traction .....	72066		6734
<b>924036; 924038; 924039</b>			
Blower .....	072108		6376
Traction .....	072098		6733
<b>924040</b>			
Blower .....	072108		6376
Traction .....	072086		6840
<b>924042; 924044</b>			
Blower .....	072108		6376
Traction .....	072066		6734
<b>924046; 924048; 924049</b>			
Blower .....	072108		6376
Traction .....	072098		6733
<b>924050; 924051; 924052; 924054</b>			
Blower .....	072108		6376
Traction .....	072066		6734
<b>924071</b>			
Auger .....	72130		6839
Traction .....	72131		6736
<b>924072</b>			
Blower .....	072086		6840
Traction .....	072066		6734
<b>924073; 924074; 924075</b>			
Blower .....	072108		6376
Traction .....	072066		6734
<b>924077</b>			
Blower .....	72108		6376
Traction .....	72066		6734

ⓉTwo Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>924080</b>			
Drive .....	72066		6734
<b>924081</b>			
Drive .....	72098		6733
<b>924082</b>			
Auger .....	72086		6840
Traction .....	72066		6734
<b>924083; 924084</b>			
Drive .....	72066		6734
<b>924085</b>			
Auger .....	72130		6839
Traction .....	72131		6736
<b>924086</b>			
Drive .....	72066		6734
<b>924087; 924091; 924092</b>			
Auger .....	72130		6839
Traction .....	72131		6736
<b>924093</b>			
Auger .....	72086		6840
Traction .....	72066		6734
<b>924100</b>			
Blower .....	72086		6840
Traction .....	72066		6734
<b>924101; 924102; 924104</b>			
Blower .....	72108		6376
Traction .....	72066		6734
<b>924105</b>			
Traction .....	72066		6734
<b>924106</b>			
Blower .....	72108		6376
Traction .....	72066		6734
<b>924108; 924109; 924110</b>			
Auger .....	72086		6840
Traction .....	72112		6735
<b>924111; 924112; 924113</b>			
Drive .....	72112		6735
<b>924115</b>			
Auger .....	72086		6840
Traction .....	72112		6735
<b>924311; 924312</b>			
Auger .....	72086		6840
Traction .....	72066		6734
<b>924313</b>			
Drive .....	72066		6734
<b>924314; 924315; 924316</b>			
Auger .....	72130		6839
Traction .....	72131		6736
<b>924317</b>			
Blower .....	72108		6376
Traction .....	72066		6734
<b>924318; 924319</b>			
Blower .....	72086		6840
Traction .....	72066		6734
<b>924323</b>			
Blower .....	72108		6376
Traction .....	72066		6734
<b>924327; 924328</b>			
Auger .....	72086		6840
Traction .....	72112		6735
<b>924329; 924330</b>			
Drive .....	72112		6735
<b>924500; 924501</b>			
Auger .....	72362		6562BR
Traction .....	72361		6736

Lawn & Garden Equipment

**SNOW BLOWERS & THROWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
926042 Drive .....	07200505		6737
926056 Drive .....	07200630		6831
926057 Brush .....	07200601	②7010BR	
926514 Drive .....	07200630		6831
926515 Brush .....	07200601	②7010BR	
926517 Drive .....	07200630		6831
932001 Blower, Ser. No. 000101 Thru 010500 .....	72107		6390
Blower, Ser. No. 010501 & After .....			6583
Drive .....	72106		6737
932004; 932006; 932007; 932015 Blower .....	72114		6583
Drive .....	72106		6737
932018 Auger .....	72117		6830
932020 Blower .....	72114		6583
Drive .....	72106		6737
932022 Auger .....	072156		6835
Drive .....	072157		6736
932026 Auger .....	72191		6837
Traction .....	72106		6737
932027 Auger .....	72192		6839
Traction .....	72157		6736
932029 Auger, Ser. No. 101 Thru 5149 .....	72253		6838
Auger, Ser. No. 5150 & After .....	72192		6839
Traction .....	72252		6737
932031 Auger, Model No. ST524 .....	72340		6838
Traction, Model No. ST524 .....	72106		6737
932032 Auger .....	72192		6839
Traction .....	72157		6736
932033; 932034 Auger .....	72325		6839
932100; 932101 Traction .....	07234000		6838
932102; 932103 Drive .....	07211400		6583
932104 Traction .....	07234000		6838
932302 Auger .....	72191		6837
Traction .....	72106		6737
932303 Auger .....	72192		6839
Traction .....	72157		6736
932304 Auger .....	72192		6839
Traction .....	72252		6737
932305 Auger .....	72340		6838
Traction .....	72106		6737
932306; 932307 Auger .....	72325		6839

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
938006 Drive .....	72321		6733
938007 Drive .....	72322		6734
938008 Drive .....	72321		6733
938009 Drive .....	72322		6734
938010 Drive .....	72321		6733
938011; 938012 Drive .....	72322		6734
938015 Drive; Model No. SS522 .....	72364		6732
938016 Drive; Model No. SS522E .....	72363		6733
938304 Drive .....	72321		6733
938305 Drive; Ser. No. 101 Thru 400 .....	72322		6734
Drive; Ser. No. 401 & After .....	72363		6733
939401 Drive .....	07200109	1210	
ST2+2 Auger .....	72114		6583
ST270; ST350; ST504 Auger .....	72114		6583
Traction .....	72106		6737
ST524 Auger .....	72108		6376
Drive .....	72106		6737
Traction .....	72098		6733
ST724 Auger; W/35" Belt O.C. ....	72156		6835
Auger; W/36" Belt O.C. ....	72108		6376
Traction .....	72098		6733
ST824 Auger .....	72086		6840
Traction .....	72066		6734
ST1032 Auger .....	72108		6376
Traction .....	72098		6733
ST1136 Auger .....	72130		6839
Traction .....	72131		6736
<b>ATLAS</b>			
15-3220 Belt .....	107042	J060293	
15-5200; 15-5210; 15-5210A; 15-5211; 15-5240; 15-5240A Belt .....			6721
826 Belt; W/38" Belt O.C. ....	10740		6838
Belt; W/40" Belt O.C. ....	10741		6840
A5211 Belt .....	107008	1210	
ESN524 Belt .....			6721
EX1116 Belt .....	421370	J060293	
SN18P; SN418P; SN420P; SN520 Belt .....			6721





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ATLAS - Continued</b>			
SN728; SN828			
Belt .....	410552		6834
<b>BAKER</b>			
722E			
Auger; Mfr. No. 1692615 .....	1674312		6837
Trans.; Mfr. No. 1692615 .....	1678600		6734
824E			
Auger; Mfr. No. 1692616 .....	1666655		6841
Disc; Mfr. No. 1692616 .....	1672732		6731
928M			
Auger; Mfr. No. 1692617 .....	1701257		6842
Disc; Mfr. No. 1692617 .....	1672732		6731
<b>BOBCAT</b>			
420; 520			
Belt .....	65082		6837
520-3; 520-5			
Auger; W/41" Belt O.C. ....	68209A		6841
Trans.; W/38" Belt O.C. ....	68208A		6838
724-5			
Auger .....	68209A		6841
Trans. ....	68208A		6838
820			
Drive; Ser. No. 10500 & Before .....			6952
Drive; Ser. No. 10501 Thru 12001 .....			3V530
Wheel Drive; Ser. No. 10500 & Before .....		2350	6835
Wheel Drive; Ser. No. 10501 Thru 12001 .....		2350	6835
Wheel Drive; Ser. No. 12002 & After .....		2350	6835
828			
Drive .....	65082		6837
Impeller .....	65098		23VX600
828-5			
Auger .....	68209A		6841
Trans. ....	68208A		6838
1020			
Wheel Drive .....			6837
1824			
Drive .....	65077		3V530
Wheel Drive .....	65082		6837
1825			
Drive .....		3640	6964
Wheel Drive .....	65032	2350	
<b>BOLENS</b>			
55-01; 55-02; 55-03; 75-01; 75-02; 75-03			
Belt .....			6736
225; 255E			
Auger .....	1737898	J060328	
523-01			
Belt .....	1185487		6732
524-09; 524-10			
Auger .....	1739943		6731
Drive .....	1739944		6837
525-01			
Belt .....	1185487		6732
532-01; 535-01			
Belt .....			6730
536-01; 536-02; 536-03; 536-04; 536-05			
Belt; W/27" Belt O.C. ....	1108460		6827
Belt; W/34" Belt O.C. ....	1715010		6834
537-01; 538-01; 539-01; 540-01			
Belt .....			6736
624-01; 624-02; 624-03			
Auger .....	1739943		6731
Drive .....	1739944		6837

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS - Continued</b>			
625			
Auger .....	1725253		6834
Drive .....	1894272		6735
724-04			
Auger .....	1739943		6731
Drive .....	1739944		6837
726			
Auger .....	1725253		6834
Drive .....	1894272		6735
726-01			
Auger .....	1725253		6834
Drive .....			6736
824-01; 824-08; 824A-01; 824A-02; 824A-03; 824B-01; 826-06; 826-07; 826-08; 826B-01			
Auger .....	1739943		6731
Drive .....	1739944		6837
832			
Auger .....	1725253		6834
Drive .....	1894272		6735
832-01			
Auger .....	1725253		6834
Drive .....			6736
1026; 1032			
Auger; W/31" Belt O.C.; W/3/8" Belt T.W. .	1739943		6731
Auger; W/34" Belt O.C.; W/1/2" Belt T.W. .	1725253		6834
Drive; W/Dual Belts .....	1739945		6837
Drive; W/Single Belt .....	1894272		6735
1032B-01			
Auger .....	1739945		6837
Drive .....	1739943		6731
4021-01; 4021-02; 4021-03			
Auger .....	1752194		6736
5210-02; 5210-03; 5210-04			
Drive .....	1746379		6736
<b>CANADA</b>			
55065			
Auger .....	18055	2300	
Traction .....	18055	2300	
55168			
Auger .....			6840
Traction .....	37169		A34
55171			
Auger .....	14790		6838
Traction .....			6837
<b>COAST TO COAST</b>			
482-5147			
Auger .....	7540222		6844
Drive .....	7540131		6671BR
482-5162; 482-5170			
Auger .....	7540194		6845
Drive .....	7540131		6671BR
<b>COLUMBIA PRODUCTS</b>			
312-100			
Belt .....	7540223		6736
312-230			
Belt .....	7540205		6673BR
312-500			
Belt; W/29" Belt O.C. ....	7540256		6729
Belt; W/38" Belt O.C. ....	7540257		6738
312-600			
Belt; W/35" Belt O.C. ....	7540131		6671BR
Belt; W/44" Belt O.C. ....	7540222		6844
312-800			
Belt; W/35" Belt O.C. ....	7540131		6671BR
Belt; W/45" Belt O.C. ....	7540194		6845

©Two Required

# SNOW BLOWERS & THROWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CRARY</b>			
<b>520</b>			
Auger .....	17690		6836
Trans. ....	17481		6830
<b>624</b>			
Auger .....	17715		6841
Trans. ....	17717		6835
<b>824</b>			
Auger; W/Honda 8 H.P. Eng. ....	17715		6841
Auger; W/Tecumseh 8 H.P. Eng.; Ser. No. 3769 & After .....	17715		6841
Trans.; W/Honda 8 H.P. Eng. ....	17792		6840
Trans.; W/Tecumseh 8 H.P. Eng.; Ser. No. 3769 & After .....	17717		6835
<b>1028</b>			
Auger; W/36" Belt O.C.; W/Tecumseh 10 H.P. Eng.; Ser. No. 5506 & Before .....	17690		6836
Auger; W/41" Belt O.C.; W/Honda 11 H.P. Eng. ....	17715		6841
Auger; W/41" Belt O.C.; W/Tecumseh 10 H.P. Eng.; Ser. No. 5507 & After .....	17715		6841
Trans.; W/30" Belt O.C.; W/Tecumseh 10 H.P. Eng.; Ser. No. 5506 & Before .....	17481		6830
Trans.; W/50" Belt O.C.; W/Honda 11 H.P. Eng. ....	17717		6835
Trans.; W/50" Belt O.C.; W/Tecumseh 10 H.P. Eng.; Ser. No. 5507 & After .....	17717		6835
<b>CUB CADET</b>			
<b>3X 26; 3X 26 HD; 3X 28; 3X 30 HD</b>			
Auger .....	954-04195A		6974BR
Wheel Drive .....	954-04201A		6619BR
<b>221 HP; 221 LHP</b>			
Auger .....	95404050		6973BR
<b>421R; 521E; 521R</b>			
Drive .....	7540101A		6517BR
<b>522E</b>			
Drive .....	7540456		6729
<b>522WE</b>			
Auger .....			②6735
Traction .....	7540343		6731
<b>524 SWE; 524 WE</b>			
Auger .....	95404050		6973BR
Wheel Drive .....	954-04260		6734
<b>526 SWE; 528 SW; 528 SWE</b>			
Auger .....	95404195		6974BR
Wheel Drive .....	954-04201A		6619BR
<b>724E</b>			
Traction .....	7540346		6411BR
<b>724TE</b>			
Auger .....			②6735
Traction .....	7540346		6411BR
<b>724WE</b>			
Auger .....			②6735
Traction .....	7540343		6731
<b>726TDE</b>			
Auger .....	95404050		6973BR
Wheel Drive .....	954-04260		6734
<b>826 4X4; 826SWE; 926E; 926SE; 926STE; 926TE</b>			
Auger .....			②6735
Traction .....	7540346		6411BR
<b>930SWE; 933SWE; 945SWE</b>			
Wheel Drive .....	954-04202	1370	
<b>1030E; 1030SE; 1030STE; 1030TE; 1130SWE; 1130TE</b>			
Auger .....			②6735
Traction .....	7540346		6411BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DEINES</b>			
<b>Marty D-1860KT</b>			
Eng. To J.S. ....			②6862
<b>DYNAMARK</b>			
<b>76-78</b>			
Auger; W/B. & S. Eng. ....	50834		6830
Auger; W/Tecumseh Eng. ....	50755		6838
Drive; W/B. & S. Eng. ....	50755		6838
Drive; W/Tecumseh Eng. ....	50754		6865
<b>79</b>			
Auger .....	50834		6830
Drive .....	51458		6839
<b>826</b>			
Auger; W/5 H.P. Eng.; W/35 1/2" Belt O.C. ....	3628		3V355
Auger; W/8 H.P. Eng.; W/50" Belt O.C. ....	3627		3V500
Traction; W/31" Belt O.C. ....	90005939		6731
<b>827</b>			
Drive .....	51458		6839
<b>828; 1026</b>			
Auger; W/5 H.P. Eng.; W/35 1/2" Belt O.C. ....	3628		3V355
Auger; W/8 H.P. Eng.; W/50" Belt O.C. ....	3627		3V500
Traction; W/31" Belt O.C. ....	90005939		6731
<b>1027</b>			
Drive .....	51458		6839
<b>1028; 1032</b>			
Auger; W/5 H.P. Eng.; W/35 1/2" Belt O.C. ....	3628		3V355
Auger; W/8 H.P. Eng.; W/50" Belt O.C. ....	3627		3V500
Traction; W/31" Belt O.C. ....	90005939		6731
<b>1033</b>			
Drive .....	51458		6839
<b>1132</b>			
Auger; W/5 H.P. Eng.; W/35 1/2" Belt O.C. ....	3628		3V355
Auger; W/8 H.P. Eng.; W/50" Belt O.C. ....	3627		3V500
Traction; W/31" Belt O.C. ....	90005939		6731
<b>1322-07</b>			
Belt; W/37" Belt O.C. ....	40899		6837
Belt; W/38" Belt O.C. ....	41740		6838
<b>1352-00; 1352-03</b>			
Belt .....	28594		6837
<b>1360-00; 1360-01; 1360-02; 1360-03; 1360-04; 1360-05; 1360-06</b>			
Belt .....	27323	2410	
<b>1360-07; 1360-08; 1360-09; 1360-10</b>			
Belt; W/37" Belt O.C. ....	40899		6837
Belt; W/38" Belt O.C. ....	41740		6838
<b>1361-00; 1361-01; 1361-02</b>			
Belt .....	27323	2410	
<b>1361-03; 1361-04</b>			
Belt .....	28594		6837
<b>1361-05</b>			
Belt .....	27323	2410	
<b>1361-06; 1361-07</b>			
Belt; W/37" Belt O.C. ....	40899		6837
Belt; W/38" Belt O.C. ....	41740		6838
<b>1361-10</b>			
Belt .....	27323	2410	
<b>1362-01; 1362-04</b>			
Belt .....	28594		6837
<b>1362-05; 1362-06</b>			
Belt .....	41740		6838
<b>1362-08; 1362-09</b>			
Belt; W/37" Belt O.C. ....	40899		6837
Belt; W/38" Belt O.C. ....	41740		6838

②Two Required



# SNOW BLOWERS & THROWERS

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
1363-00 Belt .....	43124		6829
1366-03 Belt .....	28594		6837
2350-0000; 2350-0100; 2350-0400; 2350-0500; 2350-0600; 2351-0100; 2351-0300; 2355-0000 Traction .....	53790		6737
2581-0000; 2581-0100; 2585-0000; 2585-0100; 2585-0200 Traction .....	90005938		6730
3314-0000; 3314-0100; 3314-0200; 3314-0300 Drive .....	51458		6839
5360-00; 5360-01; 5360-02; 5360-03; 5360-04 Belt .....	27323	2410	
5360-20; 5360-30 Belt .....	28594		6837
5360-31 Belt; W/37" Belt O.C. .... Belt; W/41" Belt O.C. ....	28594 27323	2410	6837
5360-32; 5360-33; 5360-36 Belt .....	28594		6837
5360-37 Belt .....	27323	2410	
5360-38 Belt .....	40899		6837
5360-39 Belt .....	28594		6837
5360-41; 5360-42 Belt .....	27323	2410	
5360-43 Belt .....	40899		6837
5360-49; 5360-51; 5360-52; 5360-53; 5360-54; 5360-55; 5360-57 Belt .....	27323	2410	
5360-76; 5360-82; 5360-83; 5360-85 Auger .....	50272		6837
Drive .....	51249		6390
5361-00; 5361-02 Belt .....	40899		6837
5361-03 Belt .....	41740		6838
5361-04; 5361-05; 5361-06; 5361-07; 5361-08; 5361-09; 5361-10; 5361-11 Belt .....	41740		6838
5361-14; 5361-16; 5361-17 Belt; W/37" Belt O.C. .... Belt; W/38" Belt O.C. ....	40899 41740		6837 6838
5361-25; 5361-27 Belt .....	49570		6837
5362-01; 5362-02; 5362-03 Belt .....	28594		6837
5362-04; 5362-05; 5362-06 Belt .....	40899		6837
5362-07; 5362-08; 5362-09; 5362-10; 5362-11; 5362-12; 5362-13; 5362-14; 5362-15; 5362-16 Belt .....	41740		6838
5362-18; 5362-19; 5362-20 Belt; W/37" Belt O.C. .... Belt; W/38" Belt O.C. ....	40899 41740		6837 6838
5418-00 Drive .....	511275M1		A100

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
5683-00; 5684-00; 5685-00; 5686-00; 5705-0100; 5705-0200 Drive .....	50935		6977
90510; 90520; 90530 Auger .....	41740		6838
Drive .....	43124		6829
CHS-826; CHS-1026; CHS-1028; CHS-1032 Drive .....			6830
CS511; CS522; CS822; CS826; CS1026; CS1028; CS1032; CS1132 Auger .....			6840
Drive .....			6839
SP100; SP100A Belt .....	SP149		6818
SP109; SP109A Belt .....	8597		6822
<b>FORD</b>			
09GN-3660 Lower Drive .....	234419		6892
Upper Drive .....	37756		6856
09GN-3665 Secondary .....	237255		6378
09GN-3679 Lower Drive .....	234419		6892
Primary .....			6866
Secondary .....	237255		6378
Upper Drive .....	235459		6853
09GN-3680 Primary .....	236914		B100
09GN-5139 Auger .....	207159		6673BR
09GN-5140 Auger .....			6732
09GN-5142 Auger .....	18055	2300	
Traction .....	18055	2300	
09GN-5143 Auger .....	14790		6838
Traction .....		2370	6837
09GN-5144 Auger .....			6840
Traction .....	37230		6838
09GN-5145 Auger .....	14790		6838
Traction .....		2370	6837
09GN-5146 Auger .....			6840
Traction .....	37230		6838
09GN-5189; 09GN-5190; 09GN-5203; 09GN-5238 Auger .....	207159		6673BR
09GN-5239 Auger .....	211664		6836
Traction .....	211650		6733
09GN-5240; 09GN-5241 Auger .....		2405	
09GN-5350 Auger .....	244105		6844
Belt .....	211650		6733
Collector .....	14790		6838
09GN-5360 Auger .....	244105		6844
420 (09JC2016) Belt .....	336055	1330	6733

Lawn & Garden Equipment

**SNOW BLOWERS & THROWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FORD - Continued</b>			
526 (09JC2650); 526 (09JC2651) Belt .....	331325		3VX400
626 (09JC2657) Belt .....	335453		6841
726 (09JC2655) Belt .....	331325		3VX400
830 (09JC2660); 830 (09JC2667) Belt .....	335453		6841
9607449 (36") Drive .....	210752		6870
Secondary .....	237255		6378
9607450 (36") Drive; W/66" Belt O.C. ....			6866
Drive; W/70" Belt O.C. ....	210752		6870
Secondary .....	237255		6378
9607459; 9607474; 9607476 Auger .....	244105		6844
ST220; ST220E Belt .....	207159		6673BR
ST320 Auger .....	211664		6836
Drive .....	207159		6673BR
Traction .....	211650		6733
ST366 Collector .....		2370	6837
ST524 Belt .....	207159		6673BR
ST526 Belt .....	207159		6673BR
Collector .....	14790		6838
Eng. To J.S. ....	18055	2300	6837
Traction .....			
ST626 Impeller .....			6841
Traction .....			6841
ST826 Belt .....	207159		6673BR
Collector .....			6840
Traction .....	37230		6838
ST826B Traction .....	244104		6734
<b>GAMBLE SKOGMO</b>			
37-4145 Auger .....	35545		6840
37-4254; 37-4255 Auger .....	18055	2300	
Traction .....	18055	2300	6830
37-4311 Auger .....	14790		6838
Traction .....		2370	6837
37-4315 Auger .....			6840
Traction .....	16146		6839
37-4322 Auger .....			6840
Traction .....	37230		6838
310-100 Drive .....	7540223		6736
310-600 Auger .....	7540222		6844
Drive .....	7540131		6671BR
310-800; 310-860; 310-960 Auger .....	7540194		6845
Drive .....	7540131		6671BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GAMBLE SKOGMO - Continued</b>			
312-210; 312-220; 312-230; 312-250; 312-300; 312-400; 312-430; 312-450 Belt .....	7540133		3V315
312-600; 312-630; 312-650; 312-700; 312-730; 312-750; 312-800; 312-830; 312-850 Belt .....	7540131		6671BR
313-205; 313-230; 313-430; 313-550; 313-570 Belt .....	7540133		3V315
313-830 Belt .....	7540131		6671BR
319-100A Drive .....	7540223		6736
8535 Belt .....	7540133		3V315
8536 Belt .....	7540131		6671BR
55141 Auger .....	35545		6840
55142 Traction .....	18055	2300	
55143 Collector .....	14790		6838
Traction .....			6837
55144 Collector .....			6840
53604900; 53605100 Belt .....	27323	2410	
53620700 Belt .....	41740		6838
<b>GILSON</b>			
90-820-01; 90-821-01; 90-822-03; 90-826-03 Auger .....	10463		6837
Traction .....	10755		6843
90-827-01 Auger .....	10463		6837
Traction .....	10463		6837
90-830-03 Auger .....	10755		6843
Traction .....	10755		6843
471 Auger .....			6838
Traction .....	16146		6837
472 Auger .....			6838
Traction .....			6837
476; 479; 490 Auger .....			6840
Traction .....	16146		6839
492 Auger .....	14790		6838
Traction .....		2370	
820; 821 Auger .....	10463		6837
Traction .....	10463		6837
822; 826; 827; 830 Auger .....	17569	2430	
Traction .....	17569	2430	
834 Auger .....	13009	2410	
Traction .....	10463		6837
835; 835C; 839 Auger .....	17569	2430	
Traction .....	17569	2430	



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
<b>841</b>			
Auger .....	13009	2410	
Traction .....	13009	2410	
<b>842</b>			
Auger .....	10463		6837
Traction .....	10463		6837
<b>844; 845</b>			
Auger .....	14790		6838
Traction .....			6837
<b>846</b>			
Auger .....			6840
Traction .....	16146		6839
<b>5001</b>			
Auger .....	14790		6838
Traction .....		2370	
<b>5002; 5004</b>			
Auger .....	17569	2430	
Traction .....	17569	2430	
<b>5005</b>			
Auger .....	13009	2410	
Traction .....	13009	2410	
<b>5006</b>			
Auger .....			6840
Traction .....	16146		6839
<b>5008</b>			
Auger .....	18055	2300	
Traction .....	18055	2300	
<b>5009</b>			
Auger .....	17569	2430	
Traction .....	17569	2430	
<b>7500</b>			
Auger .....	14790		6838
Traction .....			6837
<b>35211</b>			
Auger .....	18055	2300	
Traction .....	18055	2300	
<b>55001</b>			
Auger .....	14790		6838
Traction .....		2370	
<b>55002; 55004</b>			
Auger .....	17569	2430	
Traction .....	17569	2430	
<b>55005</b>			
Auger .....	13009	2410	
Traction .....	13009	2410	
<b>55006</b>			
Auger .....			6840
Traction .....	16146		6839
<b>55008</b>			
Auger .....	18055	2300	
Traction .....	18055	2300	
<b>55010; 55011</b>			
Auger .....	14790		6838
Traction .....		2370	
<b>55012</b>			
Auger .....	17569	2430	
Traction .....	17569	2430	
<b>55013</b>			
Auger .....	18055	2300	
Traction .....	18055	2300	
<b>55014</b>			
Auger .....			6840
Traction .....	16146		6839
<b>55015</b>			
Auger .....	14790		6838
Traction .....		2370	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
<b>55016</b>			
Auger .....			6840
Traction .....	16146		6839
<b>55017; 55018; 55019</b>			
Auger .....	17569	2430	
Traction .....	17569	2430	
<b>55020; 55026</b>			
Auger .....	18055	2300	
Traction .....	18055	2300	
<b>55036</b>			
Auger .....	35545		6840
<b>55037</b>			
Auger .....	18055	2300	
Traction .....	18055	2300	
<b>55062; 55063; 55064</b>			
Auger .....	17569	2430	
Traction .....	17569	2430	
<b>55065; 55066</b>			
Auger .....	18055	2300	
Traction .....	18055	2300	
<b>55067; 55068</b>			
Auger .....	14790		6838
Traction .....		2370	
<b>55069</b>			
Auger .....			6840
Traction .....	16146		6839
<b>55077</b>			
Auger .....	35545		6840
<b>55078</b>			
Auger .....	18055	2300	
Traction .....	18055	2300	
<b>55079</b>			
Auger .....	14790		6838
Traction .....		2370	
<b>55080</b>			
Auger .....			6840
Traction .....	16146		6839
<b>55091</b>			
Auger .....	35545		6840
<b>55092</b>			
Auger .....	18055	2300	
Traction .....	18055	2300	
<b>55093</b>			
Auger .....	14790		6838
Traction .....		2370	
<b>55095</b>			
Auger .....	14790		6838
Traction .....	37169		A34
<b>55096</b>			
Auger .....	17569	2430	
Traction .....	17569	2430	
<b>55097</b>			
Auger .....	13009	2410	
Traction .....	13009	2410	
<b>55098</b>			
Auger .....	35545		6840
<b>55100</b>			
Auger .....	14790		6838
Traction .....		2370	
<b>55129</b>			
Auger .....	207925		6732
<b>55130</b>			
Auger .....	207159		6673BR
<b>55131</b>			
Auger .....	35545		6840



**SNOW BLOWERS & THROWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>				<b>GRAINGER, W. W.</b>			
55132				3Z240			
Auger .....	18055	2300		Auger .....	10463		6837
Traction .....	18055	2300		Traction .....	10463		6837
55133				3Z756			
Auger .....	14790		6838	Auger .....	7540222		6844
Traction .....		2370		Drive .....	7540131		6671BR
55134				3Z757			
Auger .....		6840		Auger .....	7540194		6845
Traction .....	37230	6838		Drive .....	7540131		6671BR
55135				8Z753			
Auger .....	14790		6838	Belt; W/35" Belt O.C. ....	7540193		6835
Traction; W/36" Belt O.C. ....	37169		A34	Belt; W/44" Belt O.C. ....	7540222		6844
Traction; W/37" Belt O.C. ....		2370		<b>HAHN ECLIPSE</b>			
55141				7506; 7507; 7508			
Auger .....	35545		6840	Belt .....	308445		6834
55142				7513			
Auger .....	18055	2300		Belt .....	308451		6828
Traction .....	18055	2300		7547			
55143				Belt .....	308452		3V335
Auger .....	14790		6838	<b>HOMELITE</b>			
Traction .....		2370		S4			
55144				Auger .....	121078		6835
Auger .....		6840		Drive .....	1665706		6839
Traction .....	37230	6838		S8			
55174				Auger .....	161098		6839
Auger .....	18055	2300		Drive .....	174323		6761
Traction .....	18055	2300		<b>HOMKO</b>			
55175				13600100; 13600200; 13600300; 13610100;			
Auger .....	14790		6838	53600000			
Traction .....		2370		Drive .....	27323	2410	
55176				<b>HONDA</b>			
Auger .....		6840		HS35			
Traction .....	37230	6838		Auger; Belt Code SB38 .....	22431727003		6939
55179				HS50-A			
Auger .....	207159		6673BR	Auger; W/28" Belt O.C. ....	22432732013		6928
55184				Auger; W/29" Belt O.C. ....	22432732671		6929
Auger .....	13009	2410		HS55; HS55K-1			
Traction .....	13009	2410		Drive; Belt Code A-28.4 .....	22432736003		6933
55185				HS70; HS80			
Auger .....	207925		6732	Auger; Belt Code A-30.6 .....	22431738003		6833
55189; 55190; 55201; 55202; 55203				Auger; Belt Code SA-31 .....	22431738701		6832
Auger .....	207159		6673BR	Auger; Belt Code SA-32 .....	22431738A01		6833
55204				Traction; Belt Code B-33 .....	22432738831		6937
Auger .....	212183	6372		Traction; Belt Code SB-32 R.E.C. ....	22432736701		6933
Traction .....	211650	6733		Traction; Belt Code SB-33 R.E.C. ....	22432738A01		6934
55206				Traction; Belt Code SB-35 .....	22432738C31		6936
Auger .....	209375	6844		HS521			
Traction .....	212086	6840		Drive; Belt Code LA38 .....			6839
55207				HS621A; HS621AS			
Auger .....	233162	2405		Drive .....	22431747003		6839
Traction .....	212221	6839		HS624K1TA			
55208				Auger .....	22432738C31		6936
Auger .....	207159		6673BR	Traction .....	22431767003		6828
55209				HS624K1WA			
Auger .....	212183	6372		Auger .....	22432736A01		6934
Traction .....	211650	6733		Traction .....	22431767003		6828
SB4				HS724K1WA; HS724TA; HS724WA			
Auger .....	18055	2300		Auger .....	22432738C31		6936
Traction .....	18055	2300		Traction .....	22431767003		6828
SB5				HS828K1TA; HS828K1TAS; HS828K1WA;			
Auger .....	14790		6838	HS828K1WAS; HS928TA; HS928TAS;			
Traction .....		2370		HS928WA; HS928WAS			
SB8				Auger .....	22432738C31		6936
Auger .....		6840		Traction .....	22431768003		6830
Traction .....	16146	6839					



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HONDA - Continued</b>				<b>JARI</b>			
<b>HS1132TA; HS1132TAS</b>				<b>5 1/2 H.P.; 7 H.P.</b>			
Auger .....	22432V03000		6936	Belt; W/26" Belt O.C. ....	106803		6826
Traction .....	22431768003		6830	Belt; W/33 1/2" Belt O.C. ....	106804		3V335
<b>HUSQVARNA</b>				Belt; W/33" Belt O.C. ....	725100		6833
<b>ST21; ST21E</b>				<b>L1 Northland; L2 Northland</b>			
Drive .....	601001762		6735	Eng. ....	L362	2250	6825
<b>ST522H</b>				Power Unit Attachment .....	N701	2360	6836
Drive .....	601002148		6835	<b>W 2 Way</b>			
<b>ST626E</b>				Belt .....	W119	2380	6838
Auger .....	601002148		6835	<b>W-2 2 Way</b>			
Traction .....	601001437		6733	Belt .....	E119	2370	6837
<b>ST723C; ST723R</b>				<b>JOHN DEERE</b>			
Auger .....	531002630		6939	<b>320 Snow Thrower</b>			
Traction .....	531002635		6835	Drive .....	PT2303		6737
<b>ST724</b>				<b>520 Snow Thrower</b>			
Auger .....	601001437		6733	Auger; PC2022 .....	PT11878	9375	9375HD
Traction .....	601001737		6837	Auger; PC2259 .....	PT10868		6738
<b>ST824E</b>				Traction; PC2259 .....	PT10867		6729
Drive .....	601001437		6733	<b>522</b>			
<b>ST926EC</b>				Auger .....	PT11878	9375	9375HD
Blower .....	531002630		6939	Traction .....	PT11877		6735
Traction .....	531002635		6835	<b>524 Snow Thrower</b>			
<b>ST927; ST927E</b>				Auger .....	PT9738		6731
Drive .....	601001437		6733	Traction .....	PT9739		6841
<b>ST1030</b>				<b>524D</b>			
Blower .....	531002630		6939	Auger .....	M129781		6838
Traction .....	531002635		6835	Traction .....	M126984		6737
<b>JACOBSEN</b>				<b>526; 726; 732</b>			
<b>51610; 51611</b>				Auger .....	M82612		6836
Belt .....	392456		6737	Traction .....	M45613		6836
<b>52001; 52002; 52003</b>				<b>824</b>			
Eng. To P.T.O. ....	317375		6831	Auger .....	PT10869		6372
<b>52006; 52011; 52012</b>				Traction .....	PT10867		6729
Belt .....	336055	1330	6733	<b>826</b>			
<b>52600; 52601; 52610; 52611; 52612</b>				Auger .....	M82612		6836
Drive .....	331325		3VX400	Traction .....	M45613		6836
<b>52613</b>				<b>826D</b>			
Drive .....	335453		6841	Auger .....	M128890		6838
<b>52620; 52624; 52625</b>				Traction .....	M126989		6736
Drive .....	331325		3VX400	<b>826T</b>			
<b>52627; 52628; 52629</b>				Auger .....	PT10869		6372
Drive .....	335453		6841	Traction .....	PT10867		6729
<b>52630</b>				<b>828D</b>			
Drive .....	331325		3VX400	Auger .....	M124218		6837
<b>52631; 52632; 52633; 52635; 52638; 52640;</b>				Traction; Ser. No. 190000 & Before .....	M124219		6734
<b>52642; 53636</b>				<b>832</b>			
Drive .....	335453		6841	Auger .....	M82612		6836
<b>Imperial Snow Jet 20"</b>				Traction .....	M45613		6836
Drive .....	336055	1330		<b>1026; 1028</b>			
<b>Imperial Snow Jet 26"; Imperial Snow Jet 30"</b>				Auger .....	PT10866		6845
Drive .....	335453		6841	Traction .....	PT10865		6735
<b>Sno Burst</b>				<b>1032</b>			
Belt .....	392456		6737	Auger .....	M82612		6836
<b>Snow Jet 20"</b>				Traction .....	M45613		6836
Belt .....	317375		6831	<b>1032D</b>			
Eng. To P.T.O. ....	313267		6829	Auger .....	M124218		6837
Traction; W/25" Belt O.C. ....	313254	1250	6725	Traction; Ser. No. 190000 & Before .....	M124219		6734
Traction; W/29" Belt O.C. ....	314564		6829	<b>1128DDE</b>			
<b>Super Blitz</b>				Auger; Ser. No. 210000 & Before .....	M124218		6837
Belt .....	336055	1330	6733	<b>TRS21; TRS21E</b>			
				Drive; Ser. No. 160000 & Before .....	M118007		6735
				<b>TRS22</b>			
				Auger; Ser. No. 120001 & After .....	M118078		6835
				Traction .....	M118011		6733

Lawn & Garden Equipment

**SNOW BLOWERS & THROWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>TRS24</b>			
Auger; Ser. No. 140001 & After .....	M122075		6837
Traction; Ser. No. 120000 & Before .....	M110635		6736
Traction; Ser. No. 120001 & After .....	M118011		6733
<b>TRS26</b>			
Auger; Ser. No. 140000 & Before .....	M123224		6611BR
Auger; Ser. No. 140001 & After .....	M122075		6837
Traction; Ser. No. 120000 & Before .....	M110766		6736
Traction; Ser. No. 120001 & After .....	M118011		6733
<b>TRS27; TRS32</b>			
Auger; Ser. No. 140000 & Before .....	M82612		6836
Auger; Ser. No. 140001 & After .....	M122421		6837
Traction .....	M118011		6733
<b>TRX24</b>			
Auger; Ser. No. 140001 & After .....	M122075		6837
Traction; Ser. No. 140000 & Before .....	M94366		6612BR
Traction; Ser. No. 140001 & After .....	M118011		6733
<b>TRX26</b>			
Auger; Ser. No. 140000 & Before .....	M123224		6611BR
Auger; Ser. No. 140001 & After .....	M122075		6837
Traction; Ser. No. 120000 & Before .....	M110637	2300	
Traction; Ser. No. 120001 & After .....	M118011		6733
<b>K-MART</b>			
<b>315-150</b>			
Drive .....	7540226		6551BR
Impeller .....	7540257		6738
<b>315-580</b>			
Drive .....	7540256		6729
<b>LAMBERT</b>			
<b>62-54-1; 62-54F-1; 62-78-1</b>			
Belt; W/34" Belt O.C. ....	410552		6834
Belt; W/36" Belt O.C. ....	410300		6836
<b>C Dual Stage 24"; C Dual Stage 28"</b>			
Front Drive .....	410300		6836
Rear Drive .....	410301		6840
<b>HS-20</b>			
Belt .....	410267		6829
<b>HS-54; HS-54-1; HS-64F; HS-64F-1; HS-78-1; HS-78F</b>			
Belt; W/34" Belt O.C. ....	410552		6834
Belt; W/36" Belt O.C. ....	410300		6836
<b>HS-144; HS-154</b>			
Belt; W/34" Belt O.C. ....	410552		6834
Belt; W/35" Belt O.C. ....	410910		6835
<b>HS-254; HS-278</b>			
Belt .....	410552		6834
<b>HS-2524; HS-2828</b>			
Belt; W/34" Belt O.C. ....	410552		6834
Belt; W/36" Belt O.C. ....	410300		6836
<b>SN728; SN828</b>			
Belt .....	410552		6834
<b>LAWN BOY</b>			
<b>1840; 1840A</b>			
Belt .....	18055	2300	6830
<b>1850; 1851; 1871</b>			
Auger .....	207925		6732
<b>2650; 2650A; 2650B; 2650C; 2680; 2680A; 2680B; 2680C</b>			
Auger; W/5 H.P. Eng. ....	14790		6838
Auger; W/6, 7, 8 H.P. Eng. ....			6840
Traction; W/5 H.P. Eng. ....			6837
Traction; W/6, 7, 8 H.P. Eng. ....	16146		6839
<b>63679 36"</b>			
Primary .....			6866
Secondary .....	237255		6378

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>LAZY BOY</b>			
<b>25ESSP</b>			
Belt .....	1228	2280	6828
<b>25ESSP-71; 25ESSPA-73</b>			
Drive .....	1203	2310	6831
<b>BW5-20SP-79; BW5-20SP-80; BW5-20SP-81; BW5-20SP-82</b>			
Belt .....		2370	6837
<b>DLB-64; DLB-65; DLB-66; DLB-67; DLB-70; DLB-71; DLB-72; DLB-73; DLB-76</b>			
Belt .....	1228	2280	6828
<b>H5065236</b>			
Drive .....	1203	2310	6831
<b>HTV763</b>			
Belt .....	1244		6850
<b>HTV865</b>			
Belt .....	1277		6850
<b>LB20-63</b>			
Belt .....		2270	6827
<b>LBE-25; LBE-25B</b>			
Belt .....	1228	2280	6828
<b>SP17-63; SP17-64; SP17-65; SP17-66; SP17-67 S.P.</b>			
Belt .....	1206	2250	6825
<b>SPB15-62</b>			
Belt .....	1219	1180	6718
<b>SPC63</b>			
Belt .....	1206	2250	6825
<b>SPF22</b>			
Belt .....	1228	2280	6828
<b>XCS20 S.P.</b>			
Belt .....		2270	6827
<b>XCS20-64; XCS20-65</b>			
Belt .....	1228	2280	6828
<b>XCS-64; XCS-65</b>			
Belt .....	1228		6828
<b>MASSEY FERGUSON</b>			
<b>555M</b>			
Auger; Mfr. No. 1691411 .....	1674312		6837
Trans.; Mfr. No. 1691411 .....	1674308		6735
<b>755E</b>			
Auger .....	1715128		6836
Traction .....	1715591		6734
<b>860DLX</b>			
Auger .....	1701257		6842
Traction .....	1672732		6731
<b>860E; 860M</b>			
Auger; Mfr. No. 1691707, 1691374, 1691377, 1691378 .....	1672732		6731
Auger; Mfr. No. 1691708, 1691376, 1691403 .....	1676461		6733
Traction; Mfr. No. 1691707, 1691374, 1691377, 1691378 .....	1666655		6841
Traction; Mfr. No. 1691708, 1691376, 1691403 .....	1676460		6843
<b>970M</b>			
Auger; Mfr. No. 1692569, 1692570 .....	1672732		6731
Traction; Mfr. No. 1692569 .....	1701257		6842
Traction; Mfr. No. 1692570 .....	1666655		6841
<b>1080M</b>			
Auger .....	1672732		6731
Traction .....	1701257		6842
<b>MONTGOMERY WARD</b>			
<b>89-35226</b>			
Drive .....	7540133		3V315



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>180; 181</b>			
Drive; W/34 1/2" Belt O.C.; W/3/8" Belt T.W. ....	7540367		6390
Drive; W/35" Belt O.C.; W/1/2" Belt T.W. ...	7540101		6517BR
<b>190</b>			
Auger .....	7540235		6835
<b>225</b>			
Drive; W/32" Belt O.C. ....	7540205		6673BR
Drive; W/38" Belt O.C. ....	7540257		6738
<b>440; 450</b>			
Auger .....	7540256		6729
<b>471; 472</b>			
Auger .....	14790		6838
Traction .....			6837
<b>476</b>			
Auger .....			6840
Traction .....	16146	2390	6839
<b>477; 478</b>			
Drive .....	10755		6843
<b>479; 490</b>			
Auger .....			6840
Traction .....	16146	2390	6839
<b>492</b>			
Traction .....			6837
<b>498</b>			
Impeller .....	10755		6843
Traction .....	10755		6843
<b>550; 552</b>			
Auger .....	7540256		6729
Belt .....	7540257		6738
<b>586; 588</b>			
Auger .....	7540256		6729
Drive .....	7540282		6372
<b>590</b>			
Auger & Blower .....	7540357		6840
Traction .....	7540356		6735
<b>840; 850; 960</b>			
Drive; W/35 1/2" Belt O.C. ....	7540131		6671BR
Drive; W/45" Belt O.C. ....	7540194		6845
<b>GIL470A; GIL470B; GIL470C</b>			
Drive .....	18055	2300	
<b>GIL471A; GIL471B; GIL471C; GIL471D; GIL472A; GIL472B; GIL472C; GIL472D</b>			
Auger .....	14790		6838
Belt; W/39" Belt O.C. ....	16146		6839
Belt; W/40" Belt O.C. ....			6840
Traction .....		2370	6837
<b>GIL474A; GIL474B</b>			
Drive .....	18055	2300	
<b>GIL476B; GIL476C; GIL476D; GIL476E</b>			
Auger .....	14790		6838
Belt; W/39" Belt O.C. ....	16146		6839
Belt; W/40" Belt O.C. ....			6840
Traction .....		2370	6837
<b>GIL477B</b>			
Drive .....	10755		6843
Impeller .....	10755		6843
Traction .....	10755		6843
<b>GIL477C; GIL477D; GIL477E</b>			
Drive .....	10755		6843
<b>GIL478A</b>			
Drive .....	10755		6843
Impeller .....	10755		6843
Traction .....	10755		6843
<b>GIL478B; GIL478C; GIL478D</b>			
Drive .....	10755		6843

2Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>GIL478E</b>			
Drive .....	18055	2300	
<b>GIL478F</b>			
Drive; W/30" Belt O.C. ....	18055	2300	
Drive; W/43" Belt O.C. ....	10755		6843
<b>GIL479A</b>			
Collector .....			6840
Traction .....	16146		6839
<b>GIL479B; GIL479C; GIL479D; GIL479E</b>			
Auger .....	14790		6838
Belt; W/39" Belt O.C. ....	16146		6839
Belt; W/40" Belt O.C. ....			6840
Traction .....		2370	6837
<b>GIL480B</b>			
Drive .....	17569	2430	
<b>GIL490A</b>			
Collector .....			6840
Traction .....	16146		6839
<b>GIL490B; GIL490C; GIL490D; GIL490E</b>			
Auger .....	14790		6838
Belt; W/39" Belt O.C. ....	16146		6839
Belt; W/40" Belt O.C. ....			6840
Traction .....		2370	6837
<b>GIL492A; GIL492B; GIL492C</b>			
Auger .....	14790		6838
Traction .....			6837
<b>GIL498A</b>			
Drive .....	10755		6843
<b>GIL3224A</b>			
Belt .....	13072		A70
<b>GIL35211B; GIL35212A</b>			
Drive .....	18055	2300	
<b>GIL35213A; GIL35233A</b>			
Collector .....			6840
Traction .....	16146		6839
<b>GIL35235</b>			
Auger .....	35545		6840
<b>GIL35250; GIL35250A; GIL35250C; GIL35260A</b>			
Drive .....	207159		6673BR
<b>GIL35313A</b>			
Collector .....			6840
Traction .....	16146		6839
<b>GIL35621A</b>			
Auger .....	211664		6836
Traction .....	211650		6733
<b>GIL55010; GIL55011</b>			
Auger .....	14790		6838
Traction .....			6837
<b>GIL55016</b>			
Auger .....			6840
Traction .....	16146		6839
<b>SIM496A</b>			
Rotor .....	121228		6837
Trans. ....	8021077		6839
<b>SIM497A</b>			
Rotor .....	106390		6836
Trans. ....	8161244		6838
<b>SIM1245A</b>			
Belt .....	119037		6878
<b>SIM1252</b>			
Belt .....	106689		6855
<b>SIM1257B</b>			
Belt; W/26" Belt O.C. ....	106123	2255	6835
Belt; W/35" Belt O.C. ....	121078		B42
Belt; W/45" Belt O.C. ....	152017		

Lawn & Garden Equipment

**SNOW BLOWERS & THROWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
TMO31400A Auger .....	7540223		6736
TMO33339 Drive .....	7540186		6882
TMO35056A Drive; W/35 1/2" Belt O.C. .... Drive; W/45" Belt O.C. ....	7540131 7540194		6671BR 6845
TMO35151A Auger .....	7540285		6834
TMO35152A Drive .....	7540101		6517BR
TMO35154A Auger .....	7540205		6673BR
TMO35155A; TMO35156A Drive .....	7540256		6729
TMO35157A Drive; W/35 1/2" Belt O.C. .... Drive; W/45" Belt O.C. ....	7540131 7540194		6671BR 6845
TMO35160 Auger .....	7540205		6673BR
TMO35206A Belt; W/29" Belt O.C. .... Belt; W/38" Belt O.C. ....	7540256 7540257		6729 6738
TMO35219A; TMO35219B; TMO35219C; TMO35239 Auger .....	7540223		6736
TMO35253A Drive; W/35 1/2" Belt O.C. .... Drive; W/45" Belt O.C. ....	7540131 7540194		6671BR 6845
TMO35258 Belt; W/35 1/2" Belt O.C. .... Belt; W/44" Belt O.C. ....	7540131 7540222		6671BR 6844
TMO35258A Drive; W/35 1/2" Belt O.C. .... Drive; W/45" Belt O.C. ....	7540131 7540194		6671BR 6845
TMO35262A Auger .....	7540285		6834
TMO35268A; TMO35268B Drive; W/35 1/2" Belt O.C. .... Drive; W/45" Belt O.C. ....	7540131 7540194		6671BR 6845
TMO35272A Belt .....			6734
TMO35272B Auger .....	7540285		6834
TMO35273A Auger .....	7540205		6673BR
TMO35275A Belt; W/29" Belt O.C. .... Belt; W/38" Belt O.C. ....	7540256 7540251		6729 6809BR
TMO35275B Auger .....	7540257		6851
	7540256		6729
	7540251		6809BR
TMO35275C Belt; W/29" Belt O.C. .... Belt; W/38" Belt O.C. ....	7540256 7540251		6729 6809BR
TMO35282A; TMO35284A Auger .....	7540285		6834
TMO35386A Drive .....	7540205		②6673BR
TMO311230A Auger .....	7540205		6673BR
TMO313100A Auger .....	7540223		6736

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
TMO314230A Auger .....	7540205		6673BR
TMO314550; TMO314580 Auger .....	7540256		6729
TMO319180; TMO319181 Drive .....	7540101		6517BR
TMO319220; TMO319225 Drive .....	7540205		6673BR
TMO319440; TMO319450 Drive .....	7540257		6738
TMO319500 Drive .....	7540205		6673BR
TMO319552 Drive .....	7540257		6738
TMO319586; TMO319588 Drive .....	7540282		6372
ZHR-9-24575 Belt; W/43" Belt O.C. .... Belt; W/77" Belt O.C. ....	10371		6843 6977
ZYJ1363A; ZYJ1364A Belt .....	165145		②6836
<b>MTD GOLD</b>			
31AH55LH704; 31AH65LG704 Auger .....	95404195		6974BR
Wheel Drive .....	954-04201A		6619BR
31AM63KE704 Auger .....	95404050		6973BR
Wheel Drive .....	954-04260		6734
31AS2S1E704; 31AS2T5E704 Auger .....	95404050		6973BR
31BM63LF704 Auger .....	95404050		6973BR
Wheel Drive .....	954-04260		6734
<b>MTD PRODUCTS, INC.</b>			
31A-140 Auger; 1998 .....	7540367		6390
Auger; 1999 .....	7540101A		6517BR
31A-150 Auger .....	7540101A		6517BR
31AE880H; 31AE880I; 31AE983H; 31AE993I Drive .....	7540131		6671BR
191 Auger .....	7540101A		6517BR
290-180; 290-181 Auger .....	7540101		6517BR
290-225 Auger .....	7540205		6673BR
310-180; 310-181 Auger .....	7540367		6390
310-200; 310-300; 310-400; 310-500 Trans. ....	7540133		3V315
310-600; 310-600A Auger .....	7540222		6844
Trans.; W/35 1/2" Belt O.C. ....	7540131		6671BR
Trans.; W/37 1/2" Belt O.C. ....	7540132		3V375
310-700 Belt; W/35 1/2" Belt O.C. .... Belt; W/37 1/2" Belt O.C. ....	7540131 7540132		6671BR 3V375
310-800; 310-800A Auger .....	7540194		6845
Trans.; W/35 1/2" Belt O.C. ....	7540131		6671BR
Trans.; W/37 1/2" Belt O.C. ....	7540132		3V375





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>310-840; 310-850; 310-960; 310-965</b>			
Drive .....	7540131		6671BR
<b>310-976; 310-976A</b>			
Auger .....	7540194	6845	
Trans. ....	7540131	6671BR	
<b>311-100A</b>			
Auger .....	7540223	6736	
<b>311-174</b>			
Auger .....	7540101	6517BR	
<b>311-180</b>			
Auger .....	7540367	6390	
<b>311-210; 311-220</b>			
Trans. ....	7540133	3V315	
<b>311-230A</b>			
Auger .....	7540205	6673BR	
<b>311-250; 311-300; 311-400</b>			
Trans. ....	7540133	3V315	
<b>311-430A</b>			
Auger .....	7540205	6673BR	
<b>311-450</b>			
Trans. ....	7540133	3V315	
<b>311-500A</b>			
Auger .....	7540257	6738	
<b>311-600</b>			
Trans. ....	7540131	6671BR	
<b>311-600A</b>			
Auger .....	7540222	6844	
Trans. ....	7540131	6671BR	
<b>311-700; 311-750; 311-800</b>			
Trans. ....	7540131	6671BR	
<b>311-800A</b>			
Auger .....	7540194	6845	
Trans. ....	7540131	6671BR	
<b>311-840</b>			
Drive .....	7540131	6671BR	
<b>311-850</b>			
Trans. ....	7540131	6671BR	
<b>311-960A</b>			
Auger .....	7540194	6845	
Trans. ....	7540131	6671BR	
<b>311-965</b>			
Drive .....	7540131	6671BR	
<b>312-100</b>			
Auger .....	7540223	6736	
<b>312-174</b>			
Auger .....	7540101	6517BR	
<b>312-180; 312-181</b>			
Auger .....	7540367	6390	
<b>312-210; 312-220</b>			
Trans. ....	7540133	3V315	
<b>312-230</b>			
Auger .....	7540205	6673BR	
Trans. ....	7540133	3V315	
<b>312-250; 312-300; 312-400; 312-430; 312-450</b>			
Trans. ....	7540133	3V315	
<b>312-500</b>			
Auger .....	7540256	6729	
Drive .....	7540257	6738	
Trans. ....	7540257	6738	
<b>312-600</b>			
Trans.; W/35 1/2" Belt O.C. ....	7540131	6671BR	
Trans.; W/44" Belt O.C. ....	7540222	6844	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>312-630; 312-650; 312-700; 312-730; 312-750</b>			
Trans. ....	7540131		6671BR
<b>312-800</b>			
Auger .....	7540194	6845	
Trans. ....	7540131	6671BR	
<b>312-830; 312-850</b>			
Trans. ....	7540131		6671BR
<b>312-980I</b>			
Drive .....	7540131		6671BR
<b>313-100</b>			
Auger .....	7540223	6736	
<b>313-180; 313-181</b>			
Auger .....	7540367	6390	
<b>313-205</b>			
Trans. ....	7540133	3V315	
<b>313-230</b>			
Auger .....	7540205	6673BR	
Trans. ....	7540133	3V315	
<b>313-430</b>			
Trans. ....	7540133	3V315	
<b>313-500</b>			
Belt; W/29" Belt O.C. ....	7540256	6729	
Belt; W/38" Belt O.C. ....	7540257	6738	
<b>313-550; 313-570</b>			
Drive .....	7540133	3V315	
<b>313-600; 313-800</b>			
Belt; W/35 1/2" Belt O.C. ....	7540131	6671BR	
Belt; W/44" Belt O.C. ....	7540222	6844	
Belt; W/45" Belt O.C. ....	7540194	6845	
<b>313-830</b>			
Trans. ....	7540131		6671BR
<b>313-980I</b>			
Drive .....	7540131		6671BR
<b>314-100</b>			
Auger .....	7540223	6736	
<b>314-150; 314-151</b>			
Belt .....	7540273	6734	
<b>314-180; 314-181</b>			
Drive .....	7540367	6390	
<b>314-190; 314-191</b>			
Drive .....	7540101	6517BR	
<b>314-230; 314-430</b>			
Auger .....	7540205	6673BR	
<b>314-500; 314-510; 314-520; 314-550</b>			
Belt; W/29" Belt O.C. ....	7540256	6729	
Belt; W/38" Belt O.C. ....	7540257	6738	
<b>314-580</b>			
Auger .....	7540256	6729	
Drive .....	7540275	6838	
<b>314-600</b>			
Belt; W/35 1/2" Belt O.C. ....	7540131	6671BR	
Belt; W/44" Belt O.C. ....	7540222	6844	
Belt; W/45" Belt O.C. ....	7540194	6845	
<b>314-610E; 314-612E; 314-616E</b>			
Drive .....	7540343	6731	
<b>314-640F; 314-642F; 314-646F; 314-660G; 314-666G</b>			
Drive .....	7540346	6411BR	
<b>314-800; 314-860; 314-960; 314-976</b>			
Belt; W/35 1/2" Belt O.C. ....	7540131	6671BR	
Belt; W/44" Belt O.C. ....	7540222	6844	
Belt; W/45" Belt O.C. ....	7540194	6845	
<b>314-980I</b>			
Drive .....	7540131	6671BR	

Lawn & Garden Equipment

**SNOW BLOWERS & THROWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>314-9801</b>			
Belt; W/35 1/2" Belt O.C. ....	7540131		6671BR
Belt; W/45" Belt O.C. ....	7540194		6845
<b>315-140</b>			
Auger .....	7540367		6390
<b>315-144</b>			
Auger .....	7540285		6834
<b>315-150</b>			
Auger; 1985 .....	7540285		6834
Auger; 1995 .....	7540101A		6517BR
<b>315-151; 315-160</b>			
Auger .....	7540285		6834
<b>315-162</b>			
Auger .....	7540101A		6517BR
<b>315-230</b>			
Trans. ....	7540133		3V315
<b>315-230A</b>			
Auger .....	7540205		6673BR
<b>315-430</b>			
Trans. ....	7540133		3V315
<b>315-430A</b>			
Auger .....	7540205		6673BR
<b>315-450; 315-550</b>			
Belt; W/29" Belt O.C. ....	7540256		6729
Belt; W/38" Belt O.C. ....	7540257		6738
<b>315-580</b>			
Belt; W/29" Belt O.C. ....	7540256		6729
Belt; W/39" Belt O.C. ....	7540282		6372
<b>315-800</b>			
Auger .....	7540194		6845
Trans. ....	7540131		6671BR
<b>315-850; 315-850A</b>			
Auger .....	7540194		6845
Trans. ....	7540193		6835
<b>315-860</b>			
Auger .....	7540194		6845
Trans. ....	7540131		6671BR
<b>315-950; 315-950A</b>			
Auger .....	7540194		6845
Trans. ....	7540193		6835
<b>315-960</b>			
Auger .....	7540194		6845
Trans.; W/35 1/2" Belt O.C. ....	7540131		6671BR
Trans.; W/35" Belt O.C. ....	7540193		6835
<b>315-960A</b>			
Auger .....	7540194		6845
Trans. ....	7540193		6835
<b>315-980I</b>			
Drive .....	7540131		6671BR
<b>316-140</b>			
Auger .....	7540367		6390
<b>316-150</b>			
Auger; 1986 .....	7540285		6834
Auger; 1996 .....	7540101A		6517BR
<b>316-151; 316-160; 316-174</b>			
Auger .....	7540285		6834
<b>316-180; 316-181; 316-186</b>			
Auger .....	7540101		6517BR
<b>316-190</b>			
Auger .....	7540235		6835
<b>316-230A; 316-430A</b>			
Auger .....	7540205		6673BR
<b>316-440; 316-450; 316-550; 316-580</b>			
Belt; W/29" Belt O.C. ....	7540256		6729

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>316-440; 316-450; 316-550; 316-580 - Continued</b>			
Belt; W/38" Belt O.C. ....	7540257		6738
<b>316-800</b>			
Auger .....	7540194		6845
Trans. ....	7540131		6671BR
<b>316-850A; 316-950A</b>			
Auger .....	7540194		6845
Trans. ....	7540193		6835
<b>316-960</b>			
Auger .....	7540194		6845
Trans. ....	7540131		6671BR
<b>316-960A</b>			
Auger .....	7540194		6845
Trans. ....	7540193		6835
<b>316-980I</b>			
Drive .....	7540131		6671BR
<b>317-140</b>			
Auger .....	7540367		6390
<b>317-180; 317-181</b>			
Auger .....	7540101		6517BR
<b>317-190</b>			
Auger .....	7540235		6835
<b>317-440; 317-450; 317-550; 317-552</b>			
Belt; W/29" Belt O.C. ....	7540256		6729
Belt; W/38" Belt O.C. ....	7540257		6738
<b>317-586; 317-588</b>			
Traction .....	7540256		6729
<b>317-840; 317-841; 317-850</b>			
Auger .....	7540194		6845
Trans. ....	7540131		6671BR
<b>317-860</b>			
Drive .....	7540131		6671BR
<b>317-960</b>			
Auger .....	7540194		6845
Trans. ....	7540131		6671BR
<b>317E980I; 318-005</b>			
Drive .....	7540131		6671BR
<b>318-100A</b>			
Auger .....	7540223		6736
<b>318-180; 318-181</b>			
Auger .....	7540101		6517BR
<b>318-230A</b>			
Auger .....	7540205		6673BR
<b>318-300; 318-400</b>			
Trans. ....	7540133		3V315
<b>318-440; 318-450</b>			
Auger .....	7540257		6738
<b>318-500</b>			
Trans. ....	7540133		3V315
<b>318-550; 318-552</b>			
Auger .....	7540257		6738
<b>318-586; 318-588</b>			
Belt; W/38 3/4" Belt O.C. ....	7540282		6372
<b>318-600</b>			
Belt; W/35 1/2" Belt O.C. ....	7540131		6671BR
Belt; W/37 1/2" Belt O.C. ....	7540132		3V375
<b>318-600A; 318-650A</b>			
Belt; W/35" Belt O.C. ....	7540193		6835
Belt; W/44" Belt O.C. ....	7540222		6844
<b>318-700</b>			
Belt; W/35 1/2" Belt O.C. ....	7540131		6671BR
Belt; W/37 1/2" Belt O.C. ....	7540132		3V375



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>318-750A</b>			
Belt; W/35" Belt O.C. ....	7540193		6835
Belt; W/44" Belt O.C. ....	7540222		6844
<b>318-800</b>			
Belt; W/35 1/2" Belt O.C. ....	7540131		6671BR
Belt; W/37 1/2" Belt O.C. ....	7540132		3V375
<b>318-840; 318-850</b>			
Auger .....	7540194		6845
Trans. ....	7540131		6671BR
<b>318-850A</b>			
Auger .....	7540194		6845
Trans. ....	7540193		6835
<b>318-960</b>			
Auger .....	7540194		6845
Trans. ....	7540131		6671BR
<b>318-960A</b>			
Auger .....	7540194		6845
Trans. ....	7540193		6835
<b>319-100; 319-100A</b>			
Auger .....	7540223		6736
<b>319-180; 319-181</b>			
Auger .....	7540101		6517BR
<b>319-230; 319-230A</b>			
Trans. ....	7540205		6673BR
<b>319-300; 319-400</b>			
Trans. ....	7540133		3V315
<b>319-430; 319-430A</b>			
Auger .....	7540205		6673BR
<b>319-500</b>			
Trans. ....	7540133		3V315
<b>319-600; 319-600A</b>			
Belt; W/35 1/2" Belt O.C. ....	7540131		6671BR
Belt; W/35" Belt O.C. ....	7540193		6835
Belt; W/44" Belt O.C. ....	7540222		6844
<b>319-700</b>			
Trans. ....	7540131		6671BR
<b>319-800</b>			
Belt; W/35" Belt O.C. ....	7540193		6835
Belt; W/44" Belt O.C. ....	7540222		6844
Belt; W/45" Belt O.C. ....	7540194		6845
Trans. ....	7540131		6671BR
<b>319-800A</b>			
Belt; W/35" Belt O.C. ....	7540193		6835
Belt; W/44" Belt O.C. ....	7540222		6844
Belt; W/45" Belt O.C. ....	7540194		6845
<b>319-840</b>			
Drive .....	7540131		6671BR
<b>319-850</b>			
Trans. ....	7540131		6671BR
<b>319-960</b>			
Auger .....	7540194		6845
Trans. ....	7540193		6835
<b>319-960A</b>			
Belt; W/35" Belt O.C. ....	7540193		6835
Belt; W/44" Belt O.C. ....	7540222		6844
Belt; W/45" Belt O.C. ....	7540194		6845
<b>322</b>			
Traction .....	7540163	2280	6828
<b>362; 364</b>			
Traction .....	7540252	2330	6833
<b>365</b>			
Traction .....	7540292	2260	6826
<b>366</b>			
Traction .....	7540252	2330	6833

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>560</b>			
Blade .....	7540326		6862
Traction .....	7540327		6928
<b>611D</b>			
Auger .....	9540430A		②6735
Drive .....	9540343		6731
<b>612E; 613E</b>			
Drive .....	7540343		6731
<b>614E; 615D</b>			
Auger .....	9540430A		②6735
Drive .....	9540343		6731
<b>633 Thru 753; 640F; 642F; 646F; 660G</b>			
Drive .....	7540346		6411BR
<b>31960-7; 31960-8; 31960C; 31960S; 31965-9</b>			
Drive .....	7540131		6671BR
<b>E6B3H</b>			
Auger .....	9540430A		②6735
Drive .....	9540346		6411BR
<b>E600E; E610E</b>			
Auger .....	9540430A		②6735
Drive .....	9540343		6731
<b>E611D</b>			
Drive .....	7540343		6731
<b>E613E; E614E</b>			
Auger .....	9540430A		②6735
Drive .....	9540343		6731
<b>E623D</b>			
Auger .....	9540430A		②6735
Drive .....	9540456		6729
<b>E633E</b>			
Auger .....	9540430A		②6735
Drive; 1998 .....	9540346		6411BR
Drive; 1999 .....	9540456		6729
<b>E640E; E640F; E642E; E643F; E644E; E653F; E660G; E661E; E662G; E663G</b>			
Auger .....	9540430A		②6735
Drive .....	9540346		6411BR
<b>E663H; E733E; E740F; E742F; E753F; E760F; E762F</b>			
Auger .....	9540430A		②6735
Drive .....	9540346		6411BR
<b>E993I</b>			
Drive .....	9540131		6671BR
<b>TMO35153A; TMO35293A</b>			
Drive .....	7540101		6517BR
<b>MURRAY</b>			
<b>F2150-000; F2150-010; F2150-070</b>			
Drive .....	325890		6735
<b>NEW HOLLAND</b>			
<b>202114</b>			
Auger .....	18055	2300	
Drive .....	18055	2300	
<b>202115</b>			
Auger .....	14790		6838
Traction .....			6837
<b>202116</b>			
Auger .....			6840
Traction .....	16146		6839
<b>SB4</b>			
Auger .....	18055	2300	
Drive .....	18055	2300	
<b>SB5</b>			
Auger .....	14790		6838
Traction .....			6837

Lawn & Garden Equipment

**SNOW BLOWERS & THROWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NEW HOLLAND - Continued</b>			
<b>SB8</b>			
Auger .....			6840
Traction .....	16146		6839
<b>NEW IDEA</b>			
<b>38"</b>			
Drive .....	120725	3310	
<b>PENNEYS</b>			
<b>0795</b>			
Auger .....	7540194		6845
Traction .....	7540131		6671BR
<b>1295; 1337</b>			
Drive; W/29" Belt O.C. ....	7540256		6729
Drive; W/38" Belt O.C. ....	7540257		6738
<b>2407; 2408</b>			
Belt .....	1228	2280	6828
<b>2416; 2418</b>			
Belt; W/34" Belt O.C. ....	410552		6834
Belt; W/36" Belt O.C. ....	410300		6836
<b>2419; 2419A</b>			
Belt; W/34" Belt O.C. ....	410552		6834
Belt; W/35" Belt O.C. ....	410910		6835
<b>2426</b>			
Belt; W/34" Belt O.C. ....	410552		6834
Belt; W/36" Belt O.C. ....	410300		6836
<b>2429</b>			
Belt; W/34" Belt O.C. ....	410552		6834
Belt; W/35" Belt O.C. ....	410910		6835
<b>2437</b>			
Belt .....	6434		6951
<b>2439; 2439A; 2449; 2450; 2491</b>			
Belt; W/34" Belt O.C. ....	410552		6834
Belt; W/35" Belt O.C. ....	410910		6835
<b>3876</b>			
Belt .....	7540186		6882
Drive .....	7540180		6510BR
<b>4010A; 4011; 4012</b>			
Drive .....			6721
<b>4016</b>			
Auger .....	7540222		6844
Drive .....	7540193		6835
<b>4017; 4018</b>			
Auger .....	269670		6840
<b>4020</b>			
Belt .....	410910		6835
<b>4027</b>			
Auger .....	7540194		6845
Traction .....	7540131		6671BR
<b>4030</b>			
Belt .....	410552		6834
<b>4034</b>			
Auger .....	7540222		6844
Drive .....	7540131		6671BR
<b>4040</b>			
Belt .....	410552		6834
<b>POLORON</b>			
<b>9208; 9209</b>			
Belt; W/33" Belt O.C. ....	965506	3330	6933
Belt; W/45" Belt O.C. ....	965505	3450	6945
<b>9212</b>			
Main Drive .....	4335		6984
<b>121701</b>			
Belt .....	410552		6834

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>POLORON - Continued</b>			
<b>711500; 712500; 721500; 722500</b>			
Belt .....	102104		6825
<b>POULAN PRO</b>			
<b>PP208E24; PP1150E27</b>			
Impeller .....	408007		6511BR
<b>PR100</b>			
Drive .....	532437261		6517BR
<b>POWER EQUIPMENT</b>			
<b>183BSP; 204BSP; 224BSP</b>			
Belt; W/24" Belt O.C.; W/1/2" Belt T.W. ....		2240	6824
Belt; W/24" Belt O.C.; W/3/8" Belt T.W. ....		1240	6724
<b>POWERSMART</b>			
<b>DB7001; DB7005</b>			
Auger .....	302040054		7021BR
<b>DB7103; DB7103PA; DB7651; DB7651BS-24</b>			
Auger .....	302040011		6835
<b>DB7659; DB7659H</b>			
Auger .....	302040014		6826
<b>REO</b>			
<b>ST-267; ST-268</b>			
Belt; W/30" Belt O.C. ....	6552		6730
Belt; W/31" Belt O.C. ....	6551		6731
Belt; W/32" Belt O.C. ....	6506		6832
<b>ST-626A; ST-626ST; ST-626STE</b>			
Belt .....	MW10366		6836
<b>ROPER</b>			
<b>606-240; 608-260; 610-320</b>			
Auger .....	78303		6836
Traction .....	78848		6372
<b>611-321; S1749AT</b>			
Auger .....	78750		6839
Traction .....	78848		6372
<b>S6549AT</b>			
Auger .....	78303		6836
Traction .....	76672		6837
<b>S7229AR; S7229AT</b>			
Auger .....	77375		6823
Drive .....	76806		6835
<b>S8649AT; S8649BT; S9749AT; S86498T</b>			
Auger .....	78303		6836
Traction .....	76672		6837
<b>TT648AR; TT6431RO</b>			
Auger .....	1835R		6956
<b>ROTO-HOE</b>			
<b>520; 824</b>			
Impeller .....	68217E		6837
Trans. ....	68218A		6833
<b>969-1</b>			
Drive .....		2350	6835
<b>1028</b>			
Impeller .....	68217D2		6843
Trans. ....	68218A1		6838
<b>SEARS ROEBUCK</b>			
<b>131.81925; 131.81926; 131.81927; 131.81928; 131.81929</b>			
Drive .....	59311		6721
<b>247.882900; 247.882901; 247.884210</b>			
Auger .....	7540101		6517BR
<b>247.884220; 247.884221</b>			
Auger .....	7540367		6390



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>				<b>SEARS ROEBUCK - Continued</b>			
247.884410				536.882502; 536.884500			
Auger .....	7540101		6517BR	Auger .....	50272		6837
247.886640				536.884780; 536.884790			
Auger .....	7540430A		6735	Drive .....	581264		6835
Drive .....	7540343		6731	536.885010			
247.886700				Traction .....	90051458		6839
Auger .....	7540357		6840	536.885200			
247.887000				Drive .....	37X104		6857
Auger .....	754-04014		3VX265	536.885400			
Drive .....	75404013	1210		Auger .....	302706		6838
247.888160				Traction .....	302707		6734
Auger .....	7540430A		6735	536.885900			
Drive .....	7540456		6729	Drive .....	90005938		6730
247.888510				536.886140; 536.886180; 536.886190;			
Auger .....	7540256		6729	536.886260			
Drive .....	7540257		6738	Auger .....			6733
247.888530				Drive .....	581264		6835
Auger .....	7540430A		6735	536.886350			
Drive .....	7540346		6411BR	Auger .....			6733
536.8110; 536.8113				536.886440			
Drive .....		2240	6824	Auger .....			6733
536.21500				Drive .....			6835
Auger .....	41740		6838	536.886510			
536.82121				Traction .....	90053790		6737
Drive .....	SP8597	2220	6822	536.886650			
536.82200; 536.82201; 536.82201X; 536.82225;				Auger .....			6733
536.82226; 536.82228				536.887250; 536.887251; 536.887750;			
Drive .....			6820	536.887751; 536.887752; 536.887990;			
536.82230; 536.82231				536.887991; 536.887992; 536.887993;			
Drive .....	27323	2410	6841	536.887994			
536.82240				Auger .....	585416		6838
Drive .....	28594		6837	Drive .....	579932		6733
536.82400; 536.82401				536.887995			
Belt .....	40899		6837	Auger .....	585416		6838
536.82550; 536.82553; 536.82559				Drive .....	579932		6733
Drive .....			6820	536.888400			
536.88440				Auger .....			6733
Belt .....			6728	Drive .....	581264		6835
536.89187				536.899170			
Auger .....	50272		6837	Drive .....	49570		6837
536.90510; 536.90512; 536.90513				536.905602; 536.905702			
Auger .....	41740		6838	Auger .....	41740		6838
536.90514				Drive .....	40899		6837
Auger .....	41740		6838	536.905900; 536.905901; 536.905902;			
Drive .....	40899		6837	536.905903			
536.90515; 536.90520; 536.90521; 536.90523;				Auger .....	47793		6827
536.90524				536.906000; 536.906001; 536.906100;			
Auger .....	41740		6838	536.906101; 536.906200; 536.906201;			
536.90525; 536.90526; 536.90560; 536.90570				536.906300			
Auger .....	41740		6838	Auger .....	41740		6838
Drive .....	40899		6837	Drive .....	40899		6837
536.881130				536.909400; 536.909440			
Auger .....			6733	Drive .....	49570		6837
Drive .....	585416		6838	536.909700; 536.909800; 536.909900			
536.881230				Auger .....	49570		6837
Auger .....	302707		6734	536.918000; 536.918001; 536.918002;			
536.882400; 536.882401				536.918003; 536.918004			
Belt .....			6728	Auger .....	50307		6728
536.882500				Drive .....	50307		6728
Auger .....	50272		6837	536.918100			
536.882501				Auger .....	50272		6837
Drive; W/28" Belt O.C. ....			6728	Drive .....	50273		6734
Drive; W/34" Belt O.C. ....			6734	536.918101; 536.918102			
Traction .....	51249		6390	Auger .....	50272		6837
				Drive .....	51249		6390



**SNOW BLOWERS & THROWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>536.918200</b>			
Auger .....	50272		6837
Drive .....	50273		6734
<b>536.918201; 536.918202</b>			
Auger .....	50272		6837
Drive .....	51249		6390
<b>536.918300; 536.918400; 536.918500</b>			
Auger .....	49570		6837
<b>536.918700</b>			
Auger .....	50272		6837
Drive .....	51249		6390
<b>663.80853</b>			
Auger .....			6728
Drive .....			6728
<b>663.818501</b>			
Drive .....	501161	2540	6854
<b>809.82120</b>			
Drive .....	SP149		6818
<b>917.81920; 917.81921</b>			
Drive .....	5296M	1210	6721
<b>917.881550</b>			
Auger .....	585416		6838
Drive .....	579932		6733
<b>88173; 88694</b>			
Drive .....	954-04260		6734

<b>SIMPLICITY</b>			
<b>221</b>			
Drive .....	122039		6732
Rotor .....	174883		6834
<b>253; 254</b>			
Drive .....	122039		6732
Rotor .....	1657806		6836
<b>255; 256</b>			
Drive .....	1665706		6839
Rotor .....	176917		6837
<b>294; 295</b>			
Drive .....	122039		6732
Rotor .....	1657806		6836
<b>296; 297</b>			
Drive .....	1665706		6839
Rotor .....	176917		6837
<b>372</b>			
Blower .....	1665706		6839
Drive .....	106689		6855
<b>426</b>			
Drive .....	1665706		6839
Rotor .....	176917		6837
<b>428</b>			
Drive .....	122039		6732
Rotor .....	1657806		6836
<b>430</b>			
Blower .....	1665706		6839
Drive .....	106689		6855
<b>450M</b>			
Drive; Mfr. No. 1691416 .....	1674312		6837
<b>450M Export</b>			
Auger; Mfr. No. 1691417 .....	1674312		6837
<b>482; 483</b>			
Drive .....	1665706		6839
Rotor .....	121078		6835
<b>551</b>			
Blower .....	1665706		6839
Drive .....	118494		6734

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>555M</b>			
Auger; Mfr. No. 1691411 .....	1674312		6837
Auger; Mfr. No. 1692680 .....	1715128		6836
Auger; Mfr. No. 1693161, 1693425, 1693646 .....	1717393		6836
Disc; Mfr. No. 1692680, 1693161, 1693425, 1693646 .....	1715127		6735
Trans.; Mfr. No. 1691411 .....	1674308		6390
<b>555M Export</b>			
Auger; Mfr. No. 1691415 .....	1674312		6837
Trans.; Mfr. No. 1691415 .....	1674308		6390
<b>558; 559</b>			
Drive .....	1665706		6839
Rotor .....	121078		6835
<b>560</b>			
Blower .....	1665706		6839
Drive .....	106689		6855
<b>560M</b>			
Auger; Mfr. No. 1691368 .....	1701257		6842
Auger; Mfr. No. 1691374 .....	1666655		6841
Disc; Mfr. No. 1691368, 1691374 .....	1672732		6731
<b>560S</b>			
Auger; Mfr. No. 1691774 .....	1701257		6842
Disc; Mfr. No. 1691774 .....	1672732		6731
<b>643</b>			
Blower .....	156231		6842
Drive .....	170771		6736
<b>652</b>			
Blower .....	1665706		6839
Drive .....	118494		6734
<b>656</b>			
Blower .....	156231		6842
Drive .....	170771		6736
<b>742</b>			
Blower .....	1665706		6839
Drive .....	118494		6734
<b>755E</b>			
Auger; Mfr. No. 1691413 .....	1674312		6837
Auger; Mfr. No. 1692681 .....	1715128		6836
Auger; Mfr. No. 1693162, 1693426 .....	1717393		6836
Disc; Mfr. No. 1692681, 1693162, 1693426 .....	1715591		6734
Trans.; Mfr. No. 1691413 .....	1678600		6734
<b>755M</b>			
Auger; Mfr. No. 1693648 .....	1717393		6836
Disc; Mfr. No. 1693648 .....	1720234		6733
<b>755M Export</b>			
Auger; Mfr. No. 1691414 .....	1674312		6837
Auger; Mfr. No. 1692746 .....	1715128		6836
Disc; Mfr. No. 1692746 .....	1715591		6734
Trans.; Mfr. No. 1691414 .....	1678600		6734
<b>760</b>			
Auger; Mfr. No. 1691375 .....	1676460		6843
Disc; Mfr. No. 1691375 .....	1676461		6733
<b>796</b>			
Blower .....	156231		6842
Drive .....	170771		6736
<b>828</b>			
Auger; Mfr. No. 1691553 .....	1666655		6841
Disc; Mfr. No. 1691553 .....	1672732		6731
<b>860</b>			
Auger; Mfr. No. 1691401, 1691708 .....	1676460		6843
Disc; Mfr. No. 1691401, 1691708 .....	1676461		6733
<b>860 Export</b>			
Auger; Mfr. No. 1691403 .....	1676460		6843
Disc; Mfr. No. 1691403 .....	1676461		6733
<b>860DLX</b>			
Auger; Mfr. No. 1693652 .....	1701257		6842
Traction; Mfr. No. 1693652 .....	1672732		6731



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>				<b>SIMPLICITY - Continued</b>			
<b>860E</b>				<b>1690678; 1690679; 1690775; 1690776; 1690777;</b>			
Auger; Mfr. No. 1691376 .....	1676460		<b>6843</b>	<b>1690778; 1690779 – Continued</b>			
Auger; Mfr. No. 1691707 .....	1666655		<b>6841</b>	Drive; W/32" Belt O.C. ....	1666654		<b>6732</b>
Traction; Mfr. No. 1691376 .....	1676461		<b>6733</b>	<b>1690900</b>			
Traction; Mfr. No. 1691707 .....	1672732		<b>6731</b>	Drive .....	1674308		<b>6390</b>
<b>860M</b>				<b>1690903</b>			
Auger; Mfr. No. 1693650, 1693763 .....	1666655		<b>6841</b>	Blower .....	1666655		<b>6841</b>
Traction; Mfr. No. 1693650, 1693763 .....	1672732		<b>6731</b>	Drive .....	1672732		<b>6731</b>
<b>860S</b>				<b>1691023</b>			
Auger; Mfr. No. 1691778, 1691946 .....	1676460		<b>6843</b>	Blower .....	1676460		<b>6843</b>
Disc; Mfr. No. 1691778, 1691946 .....	1676461		<b>6733</b>	<b>1691368; 1691370; 1691371</b>			
<b>860SE</b>				Auger .....	1701257		<b>6842</b>
Auger; Mfr. No. 1691777, 1691900 .....	1666655		<b>6841</b>	Disc .....	1672732		<b>6731</b>
Disc; Mfr. No. 1691777, 1691900 .....	1672732		<b>6731</b>	<b>1691374</b>			
<b>869; 870</b>				Auger .....	1666655		<b>6841</b>
Blower .....	1665706		<b>6839</b>	Disc .....	1672732		<b>6731</b>
Drive .....	118494		<b>6734</b>	<b>1691375; 1691376</b>			
<b>870M</b>				Auger .....	1676460		<b>6843</b>
Auger; Mfr. No. 1691370, 1691947 .....	1701257		<b>6842</b>	Disc .....	1676461	<b>1330</b>	
Auger; Mfr. No. 1691377 .....	1666655		<b>6841</b>	<b>1691377; 1691378</b>			
Disc; Mfr. No. 1691370, 1691377, 1691947 .....	1672732		<b>6731</b>	Auger .....	1666655		<b>6841</b>
<b>870S</b>				Disc .....	1672732		<b>6731</b>
Auger; Mfr. No. 1691775, 1691898 .....	1701257		<b>6842</b>	<b>1691401; 1691403</b>			
Disc; Mfr. No. 1691775, 1691898 .....	1672732		<b>6731</b>	Auger .....	1676460		<b>6843</b>
<b>970M</b>				Disc .....	1676461	<b>1330</b>	
Auger; Mfr. No. 1692569, 1693654 .....	1701257		<b>6842</b>	<b>1691404</b>			
Auger; Mfr. No. 1692570 .....	1666655		<b>6841</b>	Drive .....	1674312		<b>6837</b>
Traction; Mfr. No. 1692569, 1692570, 1693654 .....	1672732		<b>6731</b>	<b>1691411</b>			
<b>1070M</b>				Auger .....	1674312		<b>6837</b>
Auger; Mfr. No. 1691378 .....	1666655		<b>6841</b>	Trans. ....	1674308		<b>6390</b>
Disc; Mfr. No. 1691378 .....	1672732		<b>6731</b>	<b>1691413; 1691414</b>			
<b>1080M</b>				Auger .....	1674312		<b>6837</b>
Auger; Mfr. No. 1691371, 1691948 .....	1701257		<b>6842</b>	Trans. ....	1678600		<b>6734</b>
Disc; Mfr. No. 1691371, 1691948 .....	1672732		<b>6731</b>	<b>1691415</b>			
<b>1080S</b>				Auger .....	1674312		<b>6837</b>
Auger; Mfr. No. 1691776, 1691899 .....	1701257		<b>6842</b>	Trans. ....	1674308		<b>6390</b>
Disc; Mfr. No. 1691776, 1691899 .....	1672732		<b>6731</b>	<b>1691416</b>			
<b>1180M</b>				Drive .....	1674312		<b>6837</b>
Auger; Mfr. No. 1693656 .....	1701257		<b>6842</b>	<b>1691417</b>			
Disc; Mfr. No. 1693656 .....	1672732		<b>6731</b>	Auger .....	1674312		<b>6837</b>
<b>990372</b>				<b>1691553; 1691707</b>			
Auger .....	161098		<b>6839</b>	Auger .....	1666655		<b>6841</b>
Trans. ....	106689		<b>6855</b>	Disc .....	1672732		<b>6731</b>
<b>1690209</b>				<b>1691708</b>			
Blower .....	1665706		<b>6839</b>	Auger .....	1676460		<b>6843</b>
Drive .....	118494		<b>6734</b>	Disc .....	1676461	<b>1330</b>	
<b>1690255</b>				<b>1691774; 1691775; 1691776</b>			
Blower .....	156231		<b>6842</b>	Auger .....	1701257		<b>6842</b>
Drive .....	170771		<b>6736</b>	Disc .....	1672732		<b>6731</b>
<b>1690305; 1690378</b>				<b>1691777</b>			
Drive .....	1665706		<b>6839</b>	Auger .....	1666655		<b>6841</b>
Rotor .....	1657806		<b>6836</b>	Disc .....	1672732		<b>6731</b>
<b>1690379; 1690380; 1690442</b>				<b>1691778</b>			
Blower .....	1664457		<b>6841</b>	Auger .....	1676460		<b>6843</b>
Drive .....	1667200		<b>6834</b>	Disc .....	1676461	<b>1330</b>	
<b>1690543; 1690544; 1690545; 1690546</b>				<b>1691898; 1691899</b>			
Blower .....	1666655		<b>6841</b>	Auger .....	1701257		<b>6842</b>
Drive; W/31" Belt O.C. ....	1672732		<b>6731</b>	Disc .....	1672732		<b>6731</b>
Drive; W/32" Belt O.C. ....	1666654		<b>6732</b>	<b>1691900</b>			
<b>1690586; 1690587; 1690588; 1690589</b>				Auger .....	1666655		<b>6841</b>
Blower .....	1664457		<b>6841</b>	Disc .....	1672732		<b>6731</b>
Drive .....	1667200		<b>6834</b>	<b>1691946</b>			
<b>1690678; 1690679; 1690775; 1690776; 1690777;</b>				Auger .....	1676460		<b>6843</b>
<b>1690778; 1690779</b>				Disc .....	1676461	<b>1330</b>	
Blower .....	1666655		<b>6841</b>				
Drive; W/31" Belt O.C. ....	1672732		<b>6731</b>				

# SNOW BLOWERS & THROWERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>1691947; 1691948; 1692569</b>			
Auger .....	1701257		6842
Disc .....	1672732		6731
<b>1692680</b>			
Auger .....	1715128		6836
Disc .....	1715127		6735
<b>1692681; 1692746</b>			
Auger .....	1715128		6836
Disc .....	1715591		6734
<b>1693161</b>			
Auger .....	1717393		6836
Disc .....	1715127		6735
<b>1693162</b>			
Auger .....	1717393		6836
Disc .....	1715591		6734
<b>1693425</b>			
Auger .....	1717393		6836
Disc .....	1715127		6735
<b>1693426</b>			
Auger .....	1717393		6836
Disc .....	1715591		6734
<b>1693646</b>			
Auger .....	1717393		6836
Disc .....	1715127		6735
<b>1693648</b>			
Auger .....	1717393		6836
Disc .....	1720234		6733
<b>1693650</b>			
Auger .....	1666655		6841
Disc .....	1672732		6731
<b>1693652; 1693654; 1693656</b>			
Auger .....	1701257		6842
Disc .....	1672732		6731
<b>1693763</b>			
Auger .....	1666655		6841
Disc .....	1672732		6731
<b>SNAPPER</b>			
<b>3200; 3201</b>			
Belt .....	14637		6733
<b>4220</b>			
Blower .....	15152		6835
<b>5230</b>			
Blower; W/B. & S. Eng. ....			6372
Blower; W/Tecumseh Eng. ....	13939		6376
Traction; W/B. & S. Eng. ....			6737
Traction; W/Tecumseh Eng. ....			6737
<b>5240; 5241</b>			
Blower .....	15152		6835
<b>8230; 8241</b>			
Blower; W/B. & S. Eng. ....			6372
Blower; W/Tecumseh Eng. ....	13939		6376
Traction; W/B. & S. Eng. ....			6737
Traction; W/Tecumseh Eng. ....			6737
<b>8242; 8243S</b>			
Blower; W/B. & S. Eng. ....			6838
Blower; W/Tecumseh Eng. ....	13939		6376
Traction; W/B. & S. Eng. ....			6738
Traction; W/Tecumseh Eng. ....			6736
<b>8245</b>			
Auger .....			6838
<b>8261</b>			
Blower; W/B. & S. Eng. ....			6372
Blower; W/Tecumseh Eng. ....	13939		6376
Traction; W/B. & S. Eng. ....			6737
Traction; W/Tecumseh Eng. ....			6737

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>8262; 8263S</b>			
Blower; W/B. & S. Eng. ....			6838
Blower; W/Tecumseh Eng. ....	13939		6376
Traction; W/B. & S. Eng. ....			6738
Traction; W/Tecumseh Eng. ....			6736
<b>8265; 9265</b>			
Auger .....			6838
<b>10300S; 10301</b>			
Blower; W/B. & S. Eng. ....			6372
Blower; W/Tecumseh Eng. ....	13939		6376
Traction; W/B. & S. Eng. ....			6737
Traction; W/Tecumseh Eng. ....			6737
<b>10302; 10303S</b>			
Blower; W/B. & S. Eng. ....			6838
Blower; W/Tecumseh Eng. ....	13939		6376
Traction; W/B. & S. Eng. ....			6738
Traction; W/Tecumseh Eng. ....			6736
<b>10305</b>			
Auger .....			6838
<b>C3203</b>			
Auger; Mfr. No. 55134443 .....	29604		6733
<b>EI7243</b>			
Blower .....	15152		6835
Traction .....	23416		6731
<b>EI55223; I4221; I4223; I5221; I5222; I5223; I5241; I5242</b>			
Blower .....	15152		6835
<b>I6223; I7241; I7242; I7242E; I7243</b>			
Blower .....	15152		6835
Traction .....	23416		6731
<b>I55223</b>			
Blower .....	15152		6835
<b>Large Frame</b>			
Blower; W/36 3/4" Belt O.C. ....	13939		6376
Blower; W/38" Belt O.C. ....			6838
Traction; W/36" Belt O.C. ....	29101		6736
Traction; W/38" Belt O.C. ....			6738
<b>LE Series</b>			
Blower .....	24618		6390
<b>Series 4; Series 5</b>			
Blower .....	15152		6835
<b>Series 6; Series 7</b>			
Blower .....	15152		6835
Traction .....	23416		6731
<b>SN500</b>			
Drive .....	11946		6828
<b>SN501</b>			
Drive .....	12020	2370	6837
<b>SN800</b>			
Drive .....	11948		6830
<b>SN801</b>			
Drive .....	12020	2370	6837
<b>SNOW CHAMP</b>			
<b>8461; 8481</b>			
Auger; W/38 3/4" Belt O.C. ....	7540282		6372
Auger; W/38" Belt O.C. ....	7540257		6738
Drive .....	7540256		6729
<b>STEINER TURF</b>			
<b>SB48A</b>			
Drive; W/65" Dual Belts .....	81BX62		②BX62
Drive; W/71" Dual Belts .....	81BX68		②BX68
Drive; W/Single Belt .....	81BX62		BX62
<b>SB348</b>			
Drive .....	81BX62		②BX62

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO</b>				<b>TORO - Continued</b>			
<b>521</b> Auger; Mfr. No. 38052, 38054, 38056, 38056C ..... 379080 Traction; Mfr. No. 38052, 38054, 38056, 38056C ..... 379090			<b>6589</b> <b>6729</b>	<b>31260</b> Belt; W/26", 32" Snow Blower ..... 100230			<b>6840</b>
<b>522 Power Throw</b> Drive ..... 379090			<b>6729</b>	<b>31263</b> Auger; Model No. 526, 726, 826, 832, 1032 ..... 239080 Traction; Model No. 526, 726, 826, 832, 1032 ..... 269670			<b>6840</b> <b>6840</b>
<b>522R</b> Auger; Mfr. No. 28230 ..... 379080 Drive; Mfr. No. 28230 ..... 379090			<b>6589</b> <b>6729</b>	<b>31300; 31301; 31302; 31303; 31304</b> Drive ..... 36044			<b>6829</b>
<b>622 Power Throw</b> Auger ..... 269672 Drive ..... 379090			<b>6624BR</b> <b>6729</b>	<b>31320</b> Belt; W/26", 32" Snow Blower ..... 100230			<b>6840</b>
<b>624</b> Auger; Mfr. No. 38065 ..... 269670 Traction; Mfr. No. 38065 ..... 201820			<b>6840</b> <b>6839</b>	<b>31323</b> Auger; Model No. 526, 726, 826, 832, 1032 ..... 239080 Traction; Model No. 526, 726, 826, 832, 1032 ..... 269670			<b>6840</b> <b>6840</b>
<b>624 Powershift</b> Impeller; Mfr. No. 38505 ..... 632960 Impeller; Mfr. No. 38510, 38513 ..... 632961 Traction; Mfr. No. 38505 ..... 632950 Traction; Mfr. No. 38510, 38513 ..... 632951			<b>6838</b> <b>6839</b> <b>6832</b> <b>6833</b>	<b>31506</b> Belt ..... 256430		<b>J060328</b>	
<b>0642ST07</b> Auger ..... 9750			<b>6969</b>	<b>31624; 31625</b> Auger; Model No. 524, 724 ..... 269670 Traction; Model No. 524, 724 ..... 201820			<b>6840</b> <b>6839</b>
<b>724</b> Auger; Mfr. No. 38072, 38073 ..... 269672 Traction; Mfr. No. 38072, 38073 ..... 379090			<b>6624BR</b> <b>6729</b>	<b>31626; 31660</b> Belt; W/26", 32" Snow Blower ..... 100230			<b>6840</b>
<b>724 Power Throw</b> Auger ..... 269672 Drive ..... 379090			<b>6624BR</b> <b>6729</b>	<b>31663</b> Auger; Model No. 526, 726, 826, 832, 1032 ..... 239080 Traction; Model No. 526, 726, 826, 832, 1032 ..... 269670			<b>6840</b> <b>6840</b>
<b>824</b> Auger; Mfr. No. 38080, 38085 ..... 269670 Traction; Mfr. No. 38080, 38085 ..... 201820			<b>6840</b> <b>6839</b>	<b>31677</b> Auger; Model No. 524, 724 ..... 269670 Traction; Model No. 524, 724 ..... 201820			<b>6840</b> <b>6839</b>
<b>824 Power Throw</b> Auger; Mfr. No. 38078 ..... 26-9671 Traction; Mfr. No. 38078 ..... 94-8812			<b>6839</b> <b>6588BR</b>	<b>31727</b> Belt; W/26", 32" Snow Blower ..... 100230			<b>6840</b>
<b>824 Powershift</b> Impeller; Mfr. No. 38540, 38543 ..... 632961 Traction; Mfr. No. 38540, 38543 ..... 632951			<b>6839</b> <b>6833</b>	<b>31756</b> Auger; Model No. 526, 726, 826, 832, 1032 ..... 239080 Traction; Model No. 526, 726, 826, 832, 1032 ..... 269670			<b>6840</b> <b>6840</b>
<b>824 XL Power Throw</b> Traction; Mfr. No. 38086 ..... 94-8812			<b>6588BR</b>	<b>31760</b> Belt; W/26", 32" Snow Blower ..... 100230			<b>6840</b>
<b>828 Powershift</b> Impeller; Mfr. No. 38574 ..... 632962 Traction; Mfr. No. 38570 ..... 632953 Traction; Mfr. No. 38574 ..... 632951			<b>6841</b> <b>6835</b> <b>6833</b>	<b>31763; 31813</b> Auger; Model No. 526, 726, 826, 832, 1032 ..... 239080 Traction; Model No. 526, 726, 826, 832, 1032 ..... 269670			<b>6840</b> <b>6840</b>
<b>924 Powershift</b> Auger; Mfr. No. 38547 ..... 632961 Drive; Mfr. No. 38547 ..... 632951			<b>6839</b> <b>6833</b>	<b>31820</b> Belt; W/26", 32" Snow Blower ..... 100230			<b>6840</b>
<b>1028 Powershift</b> Impeller; Mfr. No. 38555, 38556 ..... 632962 Traction; Mfr. No. 38555, 38556 ..... 632951			<b>6841</b> <b>6833</b>	<b>31823; 31995</b> Auger; Model No. 526, 726, 826, 832, 1032 ..... 239080 Traction; Model No. 526, 726, 826, 832, 1032 ..... 269670			<b>6840</b> <b>6840</b>
<b>1132 Powershift</b> Traction; Mfr. No. 38566, 38580 ..... 632953			<b>6835</b>	<b>36001; 36002; 36003</b> Drive ..... 131-1750			<b>7127BR</b>
<b>1232 Powershift</b> Impeller; Mfr. No. 38591 ..... 632967 Traction; Mfr. No. 38591 ..... 632955			<b>6841</b> <b>6834</b>	<b>37779; 37780; 37781</b> Auger ..... 120-3892 Traction ..... 120-3893			<b>6948BR</b> <b>6673BR</b>
<b>1332 Powershift</b> Auger ..... 632967 Drive ..... 632955			<b>6841</b> <b>6834</b>	<b>38000C</b> Belt; Model No. CR-20, S120; Ser. No. 990000 & After ..... 256430		<b>J060328</b>	
<b>1800</b> Auger ..... 730210			<b>5707</b>	<b>38010</b> Auger; Model No. 3521, 421, 521 ..... 379080 Traction; Model No. 3521, 421, 521 ..... 379090			<b>6589</b> <b>6729</b>
<b>1800 Powercurve</b> Drive; Mfr. No. 38025; Ser. No. 0010000- 0999999 ..... 730210			<b>5707</b>	<b>38020</b> Belt ..... 256430		<b>J060328</b>	
<b>28230</b> Auger ..... 379080 Traction ..... 379090			<b>6589</b> <b>6729</b>	<b>38025</b> Traction; Ser. No. 0000001-0999999 ..... 730210			<b>5707</b>

Lawn & Garden Equipment

**SNOW BLOWERS & THROWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>38030</b>			
Belt .....	256430	<b>J060328</b>	
<b>38035</b>			
Auger; Model No. 3521 .....	379080	<b>6589</b>	
Traction; Model No. 3521 .....	379090	<b>6729</b>	
<b>38040; 38050</b>			
Auger; Model No. 524, 724 .....	269670	<b>6840</b>	
Traction; Model No. 524, 724 .....	201820	<b>6839</b>	
<b>38052</b>			
Auger; Model No. 421, 521 .....	379080	<b>6589</b>	
Traction; Model No. 421, 521 .....	379090	<b>6729</b>	
<b>38054; 38056; 38056C</b>			
Auger .....	379080	<b>6589</b>	
Traction .....	379090	<b>6729</b>	
<b>38060</b>			
Auger; Model No. 526, 726, 826, 832, 1032 .....	239080	<b>6840</b>	
Traction; Model No. 526, 726, 826, 832, 1032 .....	269670	<b>6840</b>	
<b>38065</b>			
Auger .....	269670	<b>6840</b>	
Traction .....	201820	<b>6839</b>	
<b>38070</b>			
Auger; Model No. 526, 726, 826, 832, 1032 .....	239080	<b>6840</b>	
Traction; Model No. 526, 726, 826, 832, 1032 .....	269670	<b>6840</b>	
<b>38073</b>			
Drive .....	269670	<b>6840</b>	
<b>38078</b>			
Auger .....	26-9671	<b>6839</b>	
Traction .....	94-8812	<b>6588BR</b>	
<b>38080</b>			
Auger; Model No. 824 .....	269670	<b>6840</b>	
Traction; Model No. 824 .....		<b>6839</b>	
<b>38085; 38085C</b>			
Auger .....	269670	<b>6840</b>	
Traction .....	201820	<b>6839</b>	
<b>38086</b>			
Traction .....	94-8812	<b>6588BR</b>	
<b>38090</b>			
Auger; Model No. 826, 1132 .....	269670	<b>6840</b>	
Traction; Model No. 826, 1132 .....	176540	<b>6844</b>	
<b>38110C; 38115C</b>			
Drive .....	256430	<b>J060328</b>	
<b>38120; 38130</b>			
Belt .....	256430	<b>J060328</b>	
<b>38150</b>			
Auger; Model No. 826, 1132 .....	269670	<b>6840</b>	
Traction; Model No. 826, 1132 .....	176540	<b>6844</b>	
<b>38162</b>			
Belt .....	256430	<b>J060328</b>	
<b>38165</b>			
Belt; Model No. S620; Ser. No. 0000001 & After .....	256430	<b>J060328</b>	
<b>38170; 38171; 38175; 38176</b>			
Drive .....	759010	<b>6613BR</b>	
<b>38190</b>			
Drive; Ser. No. 0000001-2999999 .....	715380	<b>6588BR</b>	
Drive; Ser. No. 3900001-4999999 .....	715381	<b>6588BR</b>	
<b>38191</b>			
Drive; Ser. No. 2000001-2999999 .....	715380	<b>6588BR</b>	
Drive; Ser. No. 3900001-6999999 .....	715381	<b>6588BR</b>	
<b>38195</b>			
Drive; Ser. No. 0000001-2999999 .....	715380	<b>6588BR</b>	
Drive; Ser. No. 3900001-6999999 .....	715381	<b>6588BR</b>	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>38196</b>			
Drive; Ser. No. 2000001-2999999 .....	715380		<b>6588BR</b>
Drive; Ser. No. 3900001-6999999 .....	715381		<b>6588BR</b>
<b>38400; 38405</b>			
Drive .....	715381		<b>6588BR</b>
<b>38472; 38473</b>			
Drive .....	117-7733		<b>7047BR</b>
<b>38505</b>			
Impeller .....	632960		<b>6838</b>
Traction .....	632950		<b>6832</b>
<b>38510; 38513; 38540; 38543; 38547</b>			
Impeller .....	632961		<b>6839</b>
Traction .....	632951		<b>6833</b>
<b>38555; 38556</b>			
Impeller .....	632962		<b>6841</b>
Traction .....	632951		<b>6833</b>
<b>38566; 38570</b>			
Traction .....	632953		<b>6835</b>
<b>38574</b>			
Impeller .....	632962		<b>6841</b>
Traction .....	632951		<b>6833</b>
<b>38580</b>			
Traction .....	632953		<b>6835</b>
<b>38591</b>			
Impeller .....	632967		<b>6841</b>
Traction .....	632955		<b>6834</b>
<b>38700</b>			
Blower .....	1-653332		<b>6545BR</b>
Traction .....	94-8812		<b>6588BR</b>
<b>38741; 38742; 38743; 38744; 38751</b>			
Drive .....	121-6622		<b>7127BR</b>
<b>38800; 38803; 38805</b>			
Auger .....	106-4498		<b>7022BR</b>
Traction .....	94-8812		<b>6588BR</b>
<b>CCR1000</b>			
Drive; Mfr. No. 38190, 38191, 38195, 38196; Ser. No. 0010000-2999999 .....	715380		<b>6588BR</b>
Drive; Mfr. No. 38190, 38191, 38195, 38196; Ser. No. 3901000-6999999 .....	715381		<b>6588BR</b>
<b>CR-20</b>			
Drive; Mfr. No. 38115C .....	256430	<b>J060328</b>	
<b>CR-20R</b>			
Drive; Mfr. No. 38110C .....	256430	<b>J060328</b>	
<b>Power Clear 180</b>			
Drive .....	117-7733		<b>7047BR</b>
<b>Power Clear 210; Power Clear 221Q; Power Clear 421Q</b>			
Drive .....	108-4921		<b>7021BR</b>
<b>Power Max 726OE</b>			
Auger; 2012 & Older .....	106-4498		<b>7022BR</b>
Auger; 2013 & Newer .....	120-3892		<b>6948BR</b>
Traction; 2012 & Older .....	94-8812		<b>6588BR</b>
Traction; 2013 & Newer .....	120-3893		<b>6673BR</b>
<b>Power Max 826OXE; Power Max 828OXE; Power Max 1028OXE; Power Max 1128OXE</b>			
Auger .....	106-4498		<b>7022BR</b>
Traction .....	94-8812		<b>6588BR</b>
<b>Powerlite</b>			
Drive; Mfr. No. 38170, 38171, 38175, 38176 .....	759010		<b>6613BR</b>
<b>S620</b>			
Drive; Mfr. No. 38165 .....	256430	<b>J060328</b>	
<b>Snowmaster 20</b>			
Belt .....	256430	<b>J060328</b>	





Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TROY BILT</b>				<b>WESTERN AUTO - Continued</b>			
<b>5CA</b>				<b>GIS7509</b>			
Forward .....	10738		<b>6836</b>	Auger .....	233163		<b>6843</b>
<b>5GT; 5GTD; 5GTE</b>				<b>GIS7510; GIS55131</b>			
Forward .....	421321		<b>6836</b>	Auger .....	35545		<b>6840</b>
Reverse .....	421339		<b>6370</b>	<b>GIS55132</b>			
<b>31C</b>				Eng. To J.S. ....	18055	<b>2300</b>	
Drive .....	10738		<b>6836</b>	<b>GIS55133</b>			
<b>31GT; 31GTD; 31GTE; 51GTD</b>				Drive .....	14790		<b>6838</b>
Drive .....	421321		<b>6836</b>	Traction .....			<b>6837</b>
<b>53C</b>				<b>GIS55134</b>			
Drive .....	10738		<b>6836</b>	Drive .....			<b>6840</b>
<b>53GT; 53GTD; 53GTE</b>				Traction .....	37230		<b>6838</b>
Drive .....	421321		<b>6836</b>	<b>GIS55135</b>			
<b>42035</b>				Traction .....	37169		<b>A34</b>
Auger .....	1917356		<b>6836</b>	<b>WHEEL HORSE</b>			
Drive .....	1917357		<b>6735</b>	<b>4-2633; 4-2634; 4-2635; 4-2636; 4-2651;</b>			
<b>42039; 42040</b>				<b>4-2652; 4-2655</b>			
Auger .....	1772310		<b>6838</b>	Impeller .....	6506		<b>6832</b>
Drive .....	1751601		<b>6731</b>	Reverse .....	6552		<b>6730</b>
<b>GTV5-E</b>				Trans. ....	6551		<b>6731</b>
Drive .....	618819		<b>6843</b>	<b>4-2700; 4-2710; 4-2800; 4-2810</b>			
<b>SC5211B; SC5211E</b>				Traction .....	104633		<b>6836</b>
Drive .....	421412		<b>6721</b>	<b>6-7211</b>			
<b>WESTERN AUTO</b>				Spindle .....	8687		<b>6852</b>
<b>2XC7500</b>				<b>626ST; 626STE</b>			
Eng. To J.S. ....	18055	<b>2300</b>		Drive; W/33" Belt O.C. ....	MW10367		<b>6833</b>
<b>4XC5409</b>				Drive; W/36" Belt O.C. ....	MW10366		<b>6836</b>
Belt .....	10755		<b>6843</b>	<b>0642ST07</b>			
<b>4XC7500</b>				Auger .....	9750		<b>6969</b>
Drive .....	14790		<b>6838</b>	<b>ST-267; ST-268</b>			
Traction .....			<b>6837</b>	Impeller .....	6506		<b>6832</b>
<b>4XC7505</b>				Reverse .....	6552		<b>6730</b>
Belt .....	17569	<b>2430</b>		Trans. ....	6551		<b>6731</b>
<b>GIS5189</b>				<b>ST-626A</b>			
Drive .....	207159		<b>6673BR</b>	Drive; W/33" Belt O.C. ....	MW10367		<b>6833</b>
<b>GIS5408</b>				Drive; W/36" Belt O.C. ....	MW10366		<b>6836</b>
Auger .....	13009	<b>2410</b>	<b>6841</b>	<b>STR324</b>			
Traction .....	13009	<b>2410</b>	<b>6841</b>	Drive .....	1589		<b>6857</b>
<b>GIS5409</b>				<b>WHITE OUTDOOR PRODUCTS</b>			
Auger; W/40" Belt O.C. ....			<b>6840</b>	<b>66G</b>			
Auger; W/43" Belt O.C. ....	17569	<b>2430</b>		Drive .....	7540346		<b>6411BR</b>
Traction; W/39" Belt O.C. ....	16146		<b>6839</b>	<b>180; 181</b>			
Traction; W/43" Belt O.C. ....	17569		<b>6843</b>	Auger .....	7540101		<b>6517BR</b>
<b>GIS7500</b>				<b>182; 183</b>			
Auger .....	14790		<b>6838</b>	Drive .....	7540367		<b>6390</b>
Traction; Exc. Model No. A08, A87 .....			<b>6837</b>	<b>190</b>			
Traction; Model No. A08, A87 .....	18055	<b>2300</b>		Auger .....	7540101		<b>6517BR</b>
<b>GIS7503; GIS7504</b>				<b>192; 193</b>			
Drive .....	207159		<b>6673BR</b>	Drive .....	7540101A		<b>6517BR</b>
<b>GIS7505</b>				<b>440; 450; 550; 552</b>			
Auger .....			<b>6840</b>	Auger; W/29" Belt O.C. ....	7540256		<b>6729</b>
Traction .....	16146	<b>2390</b>	<b>6839</b>	Auger; W/38" Belt O.C. ....	7540257		<b>6738</b>
<b>GIS7506</b>				<b>586; 588</b>			
Auger .....	211664		<b>6836</b>	Drive .....	7540282		<b>6372</b>
Traction .....	211650		<b>6733</b>	<b>616E</b>			
<b>GIS7507</b>				Drive .....	7540343		<b>6731</b>
Auger; W/40" Belt O.C. ....			<b>6840</b>	<b>646F; 648F</b>			
Auger; W/43" Belt O.C. ....	17569	<b>2430</b>		Drive .....	7540346		<b>6411BR</b>
Traction; W/39" Belt O.C. ....	16146		<b>6839</b>	<b>800; 840; 841; 850; 960</b>			
Traction; W/43" Belt O.C. ....	17569		<b>6843</b>	Auger .....	7540194		<b>6845</b>
<b>GIS7508</b>				Drive; W/35 1/2" Belt O.C. ....	7540131		<b>6671BR</b>
Drive .....			<b>6840</b>	Drive; W/45" Belt O.C. ....	7540194		<b>6845</b>
Traction .....	37230		<b>6838</b>				

Lawn & Garden Equipment

**SNOW BLOWERS & THROWERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE OUTDOOR PRODUCTS - Continued</b>			
990-058			
Auger .....	320002003		3V315
990-111			
Drive; W/35" Belt O.C. ....	320033596		6835
Drive; W/45" Belt O.C. ....	320044113		6845
990-150			
Auger .....	7540223		6736
990-170			
Belt; W/35" Belt O.C. ....	7540193		6835
Belt; W/44" Belt O.C. ....	7540222		6844
990-178			
Auger .....	7540222		6844
Drive .....	7540131		6671BR
990-180; 990-181			
Auger .....	7540194		6845
Drive .....	7540131		6671BR
990-245; 994-066			
Auger .....	7540223		6736
994-170			
Auger .....	7540222		6844
Drive .....	7540131		6671BR
994-178			
Auger .....	7540194		6845
Drive .....	7540131		6671BR
Snow Boss 300			
Auger .....	7540223		6736
<b>YAMAHA</b>			
YS624			
Drive; W/32" Belt O.C. ....	7Y64624200		6932
Drive; W/33" Belt O.C. ....	7Y64624210		6933
<b>YANMAR</b>			
YT3600			
Deck Drive .....			6965
<b>YARD MACHINES</b>			
31A-140			
Drive .....	7540367		6390
31A-150			
Drive .....	7540101A		6517BR
31A-611D			
Auger .....			②6735
Drive .....	7540343		6731
31AE6A4E			
Auger .....			②6735
Drive .....	7540346		6411BR
31AE150			
Drive .....	7540101A		6517BR
31AE600E; 31AE610E; 31AE640F; 31AE644E; 31AE662E; 31AE664F			
Auger .....			②6735
Drive .....	7540343		6731
31AE740F			
Auger .....			②6735
Drive .....	7540346		6411BR
317-140			
Drive .....	7540367		6390
317-150			
Drive .....	7540101A		6517BR
317-611D			
Auger .....			②6735
Drive .....	7540343		6731
317E140			
Drive .....	7540367		6390

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD MACHINES - Continued</b>			
317E150			
Drive .....	7540101A		6517BR
317E610E; 317E640F; 317E644E; 317E664F			
Auger .....			②6735
Drive .....	7540343		6731
317E740F			
Auger .....			②6735
Drive .....	7540346		6411BR
317E980I			
Auger .....	7540194		6845
Drive .....	7540131		6671BR
<b>YARD-MAN</b>			
311-183; 311-184			
Auger .....	7540367		6390
311-345			
Auger .....	7540282		6372
Drive .....	7540256		6729
311-355			
Auger; W/38 3/4" Belt O.C. ....	7540282		6372
Auger; W/77" Belt O.C. ....	7540338		6877
Drive .....	7540256		6729
311-385			
Auger .....	7540282		6372
Drive .....	7540338		6877
311-965			
Auger .....	7540194		6845
Drive .....	7540131		6671BR
31100-0; 31100-1; 31100-8; 31100-9			
Auger .....	7540223		6736
31150; 31151; 31160			
Belt .....	7540285		6834
31250			
Belt .....	7540205		6673BR
31352; 31353; 31382; 31383; 31384			
Auger .....	7540282		6372
Drive .....	7540256		6729
31515; 31515-1; 31550			
Auger .....	7540257	1380	6738
Drive .....	7540256		6729
31600-1; 31650-1			
Auger .....	7540222		6844
Drive .....	7540131		6671BR
31800; 31850			
Belt .....	7540131		6671BR
31860; 31960; 31976			
Auger .....	7540194		6845
Drive .....	7540131		6671BR
E6B3H			
Drive .....	7540346		6411BR
E162E			
Auger .....	7540101A		6517BR
E573H			
Drive .....	7540346		6411BR
E623; E623D; E623E; E633E; E633H; E653F; E663E; E663H; E673H; E733E			
Auger .....			②6735
Drive .....	7540346		6411BR
E733F; E753F; E763G			
Auger .....			②6735
Drive .....	7540346		6411BR
E983H; E993I			
Auger .....	7540222		6844
H763G			
Auger .....			②6735

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD-MAN - Continued</b>			
<b>H763G – Continued</b>			
Drive .....	7540346		6411BR

Lawn & Garden Equipment



Manufacturers' Part Number Shown for Reference Only

Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE</b>				<b>ACE HARDWARE - Continued</b>			
<b>21A-415A</b>				<b>215-200; 215-255 - Continued</b>			
Drive .....	7540438		6851	Reverse .....	7540106		6825
<b>210-030</b>				<b>215-310</b>			
Drive .....	7540216		6729	Drive .....	7540190		6839
<b>210-320</b>				<b>215-355</b>			
Drive .....	7540190		6839	Forward .....	7540154	2370	6837
<b>210-350</b>				Reverse .....	7540189	2440	6844
Forward .....	7540121		6831	<b>215-381</b>			
Reverse .....	7540146		6833	Forward .....	7540154	2370	6837
<b>210-355</b>				Reverse .....	7540201	2410	6841
Forward .....	7540154		6837	<b>215-405</b>			
Reverse .....	7540189		6844	Forward .....	7540109		6843
<b>210-360</b>				Reverse .....	7540195		6854
Forward .....	7540121		6831	<b>215-412</b>			
Reverse .....	7540146		6833	Eng. To Variator .....	7540220		6927
<b>210-385</b>				Variator To Gear Box .....	7540268		6951
Forward .....	7540154		6937	<b>216-031</b>			
Reverse .....	7540201		6841	Drive .....	7540216	1290	6729
<b>211-355; 211-360</b>				<b>216-033</b>			
Forward .....	7540121		6831	Drive .....	7540190		6839
Reverse .....	7540146		6833	<b>216-100</b>			
<b>211-370</b>				Drive .....	7540196		6830
Forward .....	7540154		6837	<b>216-200</b>			
Reverse .....	7540155		6509BR	Forward .....	7540196		6830
<b>212-355; 212-360</b>				Reverse .....	7540106		6825
Forward .....	7540121		6831	<b>216-260</b>			
Reverse .....	7540146		6833	Forward .....	7540104		6832
<b>212-375</b>				Reverse .....	7540103		6827
Belt; W/28" Belt O.C. ....	7540157		6928	<b>216-310</b>			
Belt; W/35" Belt O.C. ....	7540158		6935	Drive .....	7540190		6839
<b>213-200</b>				<b>216-355</b>			
Forward .....	7540107		6830	Forward .....	7540154	2370	6837
Reverse .....	7540189		6844	Reverse .....	7540189	2440	6844
<b>213-360</b>				<b>216-360</b>			
Forward .....	7540177		6832	Forward .....	7540104		6832
Reverse .....	7540146		6833	Reverse .....	7540103		6827
<b>213-380</b>				<b>216-380; 216-381; 216-385</b>			
Eng. To Variator .....	7540157	3280	6928	Forward .....	7540154	2370	6837
Forward .....	7540154		6837	Reverse .....	7540201	2410	6841
Reverse .....	7540155		6509BR	<b>216-405</b>			
Variator To Trans. ....	7540158	3350	6935	Forward .....	7540109		6843
<b>214-031</b>				Reverse .....	7540195		6854
Drive .....	7540216		6729	<b>216-412</b>			
<b>214-200</b>				Eng. To Variator .....	7540220		6927
Forward .....	7540107		6830	Variator To Gear Box .....	7540268		6951
Reverse .....	7540189		6844	<b>217-020; 217-031</b>			
<b>214-310</b>				Drive .....	7540216		6729
Drive .....	7540190	2390	6839	<b>217-310</b>			
<b>214-355</b>				Drive .....	7540190		6839
Forward .....	7540154		6837	<b>217-355</b>			
Reverse .....	7540189		6844	Forward .....	7540154		6837
<b>214-381</b>				Reverse .....	7540189		6844
Forward .....	7540154		6937	<b>217-381; 217-385</b>			
Reverse .....	7540201		6841	Forward .....	7540154		6937
<b>214-385</b>				Reverse .....	7540201		6841
Drive .....	7540192		6834	<b>217-430</b>			
<b>214-405</b>				Drive .....	7540325		6857
Forward .....	7540109		6843	<b>218-020A; 218-030; 218-030A</b>			
Reverse .....	7540195		6854	Drive .....	7540216		6729
<b>215-031</b>				<b>218-350</b>			
Drive .....	7540216		6729	Forward .....	7540104		6832
<b>215-200; 215-255</b>				Reverse .....	7540103		6827
Forward .....	7540196		6830				



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE - Continued</b>			
<b>218-355</b>			
Forward .....	7540154	2370	6837
Reverse .....	7540189	2440	6844
<b>218-365</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>219-030</b>			
Drive .....	7540216		6729
<b>219-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>219-385</b>			
Forward .....	7540154		6937
Reverse .....	7540201		6841
<b>70406</b>			
Forward .....	7540154	2370	6837
Reverse .....	7540189	2440	6844
<b>72070</b>			
Drive .....	7540216	1290	6729
<b>72071</b>			
Drive .....	7540190	2390	6839
<b>72237</b>			
Drive .....	7540103		6827
<b>72238</b>			
Forward .....	7540196		6830
Reverse .....	7540106		6825
<b>72568</b>			
Eng. To Variator .....	7540157		6928
Variator .....	7540158		6935
<b>73528</b>			
Tine .....	7540325		6857
<b>AGWAY</b>			
<b>82-0021</b>			
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/51" Belt O.C. ....	7540268		6951
<b>82-1012</b>			
Drive .....	7540216		6729
Forward; 1972-1971 .....	7540121	2310	6831
Reverse; 1972-1971 .....	7540146	2330	6833
<b>82-1013</b>			
Forward; 1971 .....	7540154	2370	6837
Forward; 1977-1976 .....	7540196	2300	6830
Reverse; 1971 .....	7540155		6509BR
Reverse; 1977-1976 .....	7540106	2250	6825
<b>82-1014</b>			
Drive; 1975-1974 .....	7540192	2340	6834
Eng. To Variator; 1973-1972 .....	7540157	3280	6928
Forward .....	7540154		6837
Reverse .....	7540201		6841
Variator To Trans.; 1973-1972 .....	7540158	3350	6935
<b>82-1015</b>			
Drive .....	7540196		6830
<b>82-1016</b>			
Drive .....	7540190		6839
<b>82-1017</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>82-1020</b>			
Drive .....	7540190		6839
<b>82-1021</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>82-1022</b>			
Forward .....	7540109		6843
Reverse .....	7540195		6854

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AGWAY - Continued</b>			
<b>82-1040</b>			
Drive .....	7540325	2570	6857
<b>210-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>210-350; 210-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>211-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>211-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>211-370</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>212-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>212-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>213-200; 214-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>214-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>214-385</b>			
Belt .....	7540192		6834
<b>215-381</b>			
Forward .....	7540154	2370	6837
Reverse .....	7540201	2410	6841
<b>216-402</b>			
Tine .....	7540195		6854
Variable Speed .....	7540207		6842
<b>217-402</b>			
Drive .....	7540207		6842
<b>217-430</b>			
Drive .....	7540325		6857
<b>219-200</b>			
Forward .....	7540107	2300	6830
Reverse .....	7540106	2250	6825
<b>219-350; 219-360</b>			
Forward .....	7540103		6827
Reverse .....	7540121		6831
<b>ALDENS</b>			
<b>10-203-10</b>			
Forward .....	1110		6835
<b>210-100</b>			
Belt .....	7540103		6827
<b>213-370; 213-375</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>213-380; 213-385</b>			
Belt .....	7540158		6935
<b>214-370</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>214-375</b>			
Forward .....	7540190		6839
Reverse .....	7540189		6844

Lawn & Garden Equipment





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALDENS - Continued</b>			
<b>218-360</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>548</b>			
Forward .....	7740		6838
Reverse .....	7838		6734
<b>549; 555</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>6025A</b>			
Forward .....	7540121		6831
Reverse .....	7540126		6820
<b>6040A</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>6065A; 6081B</b>			
Forward .....	7540121		6831
Reverse .....	7540126		6820
<b>6110A; 6110B</b>			
Belt .....	7540138		6950
<b>9077A; 9080</b>			
Belt .....	7540103		6827
<b>9080E</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>9083A; 9083C</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>9084</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>9679B; 9679R; 9680R</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>A-555; B-555</b>			
Forward .....		2370	6837
Reverse .....		1390	6739
<b>FS42-6015A</b>			
Forward .....	7540121	2310	6831
Reverse .....	7540146	2330	6833
<b>FS42-6040A; FS42-6081B</b>			
Forward .....	7540154	2370	6837
Reverse .....	7540155		6509BR
<b>FS42-6110A; FS42-6110B</b>			
Eng. To Variator .....	7540157	3280	6928
Variator To Trans. ....	7540158	3350	6935
<b>FS42-9077A; FS42-9080; FS42-9080D</b>			
Drive .....	7540103	2270	6827
<b>FS42-9080E</b>			
Forward .....	7540107	2300	6830
Reverse .....	7540106	2250	6825
<b>FS42-9083</b>			
Forward; W/31" Belt O.C. ....	7540121	2310	6831
Forward; W/32" Belt O.C. ....	7540104	2320	6832
Reverse; W/27" Belt O.C. ....	7540103	2270	6827
Reverse; W/33" Belt O.C. ....	7540146	2330	6833
<b>FS42-9083A; FS42-9083C</b>			
Forward .....	7540104	2320	6832
Reverse .....	7540106	2250	6825
<b>FS42-9084</b>			
Forward .....	7540107	2300	6830
Reverse .....	7540106	2250	6825
<b>FS42-60651</b>			
Forward .....	7540154	2370	6837
Reverse .....	7540155		6509BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIED HARDWARE</b>			
<b>210-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>210-350; 210-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>211-200; 211-350; 212-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>212-355; 212-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>212-375</b>			
Belt .....	7540109		6843
<b>213-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>213-355; 213-360</b>			
Forward .....	7540177		6832
Reverse .....	7540146		6833
<b>214-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>214-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>214-380; 214-385</b>			
Belt .....	7540192		6834
<b>218-350; 218-360</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>ALLIS-CHALMERS</b>			
<b>2 H.P.</b>			
Belt .....	1663009		6728
<b>3 H.P.</b>			
Belt .....	2029748	2338	
<b>5 H.P.</b>			
Forward .....	2027168		6834
Reverse .....	1667200		6734
<b>8 H.P.</b>			
Forward .....	2029829		6837
Reverse .....	2029828		6737
<b>2024760</b>			
Belt .....	200554		6846
<b>2029975</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>2029976</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>AMERICAN HARDWARE</b>			
<b>212-375; 212-380; 20957</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>27191</b>			
Belt .....	7540103		6827
<b>39514</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>Belair 212-200; Belair 213-200</b>			
Belt .....	7540103		6827
<b>Brandywine</b>			
Drive .....	7540216		6729



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AMERICAN HARDWARE - Continued</b>			
<b>Cumberland 212-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>Cumberland 213-360</b>			
Forward .....	7540177		6832
Reverse .....	7540146		6833
<b>Cumberland 214-360</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>Midland 214-380</b>			
Belt .....	7540192		6834
<b>Servistar 210-030</b>			
Belt .....	7540103		6827
<b>Servistar 210-320</b>			
Drive .....	7540190		6839
<b>Servistar 210-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>Servistar 210-385</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>Servistar 210-405</b>			
Drive .....	7540224		6926
Variable Speed .....	7540221		6952
<b>Servistar 216-031</b>			
Belt .....	7540103		6827
<b>Servistar 15227</b>			
Drive .....	7540224		6926
Variable Speed .....	7540221		6952
<b>SSR031</b>			
Tine .....	7540195		6854
<b>SSR381</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>SSR404; SSR405</b>			
Tine .....	7540195		6854
Variator .....	7540190		6839
<b>Vanderbilt 214-385</b>			
Belt .....	7540192		6834
<b>AMERICAN HARDWARE SERVISTAR</b>			
<b>217-020</b>			
Drive .....	7540216	1290	6729
<b>15337</b>			
Eng. To Variator .....	7540224	3260	6926
Variator To Drive .....	7540221	3520	6952
<b>27191</b>			
Drive .....	7540216	1290	6729
<b>39514</b>			
Forward .....	7540154	2370	6837
Reverse .....	7540201	2410	6841
<b>ARIENS</b>			
<b>23B</b>			
Forward .....	072056		6832
<b>23C-3B</b>			
Forward .....	072056		6832
Reverse .....	072099		6731
<b>23L; 23LS</b>			
Forward .....	072056		6832
<b>24B</b>			
Forward .....	072056		6832
Reverse .....	072043		6732
<b>24C3L</b>			
Forward .....	072056		6832

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>24C4B</b>			
Forward .....	072056		6832
Reverse .....	072043		6732
<b>24C5L</b>			
Forward .....	072056		6832
Reverse .....	072099		6731
<b>24L; 24LE</b>			
Forward .....	072056		6832
Reverse .....	072043		6732
<b>25L; 2980; 2984</b>			
Forward .....	072056		6832
Reverse .....	072099		6731
<b>2985; 2990</b>			
Forward .....	072056		6832
Reverse .....	072043		6732
<b>92009</b>			
Forward .....	072056		6832
Reverse .....	072085		6732
<b>92010</b>			
Forward .....	072056		6832
<b>92011; 92012</b>			
Forward .....	072056		6832
Reverse .....	072099		6731
<b>92013; 92015; 92016</b>			
Forward .....	072056		6832
<b>901001; 901002; 901003</b>			
Forward .....	072046		6731
Reverse .....	072024		6829
<b>901004; 901005</b>			
Forward .....	072093		6831
Reverse .....	072024		6829
<b>901006</b>			
Forward .....	072046		6731
Reverse .....	072024		6829
<b>901007; 901008</b>			
Forward .....	072046		6731
Reverse .....	072119		6830
<b>901009</b>			
Forward; W/31" Belt O.C. ....	072046		6731
Forward; W/36" Belt O.C. ....	072126		6736
Reverse; W/30" Belt O.C. ....	072119		6830
Reverse; W/41" Belt O.C. ....	072127		6741
<b>901011</b>			
Forward .....	072119		6830
Reverse .....	072106		6737
<b>901012</b>			
Forward .....	072046		6731
Reverse .....	072106		6737
<b>901013</b>			
Forward .....	072126		6736
Reverse .....	072127		6741
<b>901015; 901016</b>			
Forward .....	072119		6830
Reverse .....	072106		6737
<b>901017</b>			
Forward .....	072046		6731
Reverse .....	072106		6737
<b>901018</b>			
Forward .....	072126		6736
Reverse .....	072127		6741
<b>902001; 902002</b>			
Forward .....	072056		6832
<b>902003</b>			
Forward .....	072056		6832
Reverse .....	072099		6731

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>902004</b>			
Forward .....	072056		6832
Reverse .....	072043		6732
<b>902005; 902006</b>			
Forward .....	072056		6832
Reverse .....	072099		6731
<b>902007</b>			
Trans .....	072073		6831
<b>902008; 902010; 902013</b>			
Forward .....	072056		6832
<b>902014</b>			
Trans .....	072073		6831
<b>902015; 902016</b>			
Forward .....	072056		6832
<b>902017</b>			
Forward .....	072056		6832
Reverse .....	072099		6731
<b>902018</b>			
Forward .....	072056		6832
Reverse .....	072085		6732
<b>902019</b>			
Forward .....	072056		6832
Reverse .....	072043		6732
<b>902020</b>			
Forward .....	072056		6832
<b>902022</b>			
Trans .....	072073		6831
<b>902024</b>			
Forward .....	072056		6832
Reverse .....	072099		6731
<b>902025</b>			
Forward .....	072056		6832
<b>902026</b>			
Forward .....	072056		6832
Reverse .....	072099		6731
<b>902803; 902804; 902805</b>			
Belt .....	072109		6832
<b>902980; 902984</b>			
Forward .....	072056		6832
Reverse .....	072099		6731
<b>902985</b>			
Forward .....	072056		6832
Reverse .....	072043		6732
<b>FT214; FT314</b>			
Drive .....	72056		6832
Reverse; W/31" Belt O.C. ....	72099		6731
Reverse; W/32" Belt O.C. ....	72085		6732
<b>FT316</b>			
Drive; Mfr. No. 902808 .....	72056		6832
<b>FT320; FT424</b>			
Drive .....	72056		6832
Reverse; W/31" Belt O.C. ....	72099		6731
Reverse; W/32" Belt O.C. ....	72085		6732
<b>FT516</b>			
Drive; Mfr. No. 902810 .....	72056		6832
Forward; Mfr. No. 902410 .....	72056		6832
Reverse; Mfr. No. 902410 .....	72085		6732
<b>FT524</b>			
Drive .....	72056		6832
Forward; Mfr. No. 902018, 902418 .....	72056		6832
Reverse; Mfr. No. 902018, 902418 .....	72085		6732
Reverse; W/31" Belt O.C. ....	72099		6731
Reverse; W/32" Belt O.C. ....	72085		6732
<b>FT524R</b>			
Forward; Mfr. No. 902501 .....	72056		6832
Reverse; Mfr. No. 902501 .....	72373		6730

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>RT5018</b>			
Forward; Mfr. No. 901025, 901428 .....	72241		B48
P.T.O.; W/27" Belt O.C. ....	72241		B48
P.T.O.; W/28" Belt O.C. ....			6728
Reverse; Mfr. No. 901025, 901428 .....	72330		6727
<b>RT5020</b>			
P.T.O.; W/29" Belt O.C. ....	72024		6829
P.T.O.; W/31" Belt O.C. ....	72046		②6731
<b>RT6018</b>			
P.T.O.; W/27" Belt O.C. ....	72241		B48
P.T.O.; W/28" Belt O.C. ....			6728
<b>RT6020</b>			
P.T.O.; W/31" Belt O.C. ....	72046		6731
P.T.O.; W/37" Belt O.C. ....	72106		②6737
<b>RT7020</b>			
P.T.O.; W/29" Belt O.C. ....	72024		6829
P.T.O.; W/31" Belt O.C. ....	72046		②6731
<b>RT8020</b>			
Forward; Mfr. No. 901024, 901429 .....	72316		②6737
P.T.O.; W/36" Belt O.C. ....	72126		6736
P.T.O.; W/41" Belt O.C. ....	72127		6741
Reverse; Mfr. No. 901024, 901429 .....	72127		6741
<b>ATLAS</b>			
<b>5-26</b>			
Forward .....	107037		6831
Reverse .....	107037		6831
<b>12-2100</b>			
Belt .....	107038		6836
<b>12-3010; 12-3011</b>			
Belt .....	10737		6831
<b>12-3100</b>			
Belt .....	107038		6836
<b>12-3150</b>			
Belt .....	10721		6967
<b>12-5010</b>			
Belt .....	10737		6831
<b>12-5011</b>			
Forward .....	107037		6831
Reverse .....	107038		6836
<b>12-5012; 12-5013</b>			
Belt .....	10737		6831
<b>12-5015; 12-5016; 12-5020; 12-5021; 12-5022</b>			
Forward .....	107037		6831
Reverse .....	107038		6836
<b>12-5100</b>			
Forward .....	107038		6836
Reverse .....	107039		6370
<b>22-3150; 22-5350</b>			
Belt .....	107038		6836
<b>23-5000</b>			
Belt .....	622407		6950
<b>23-5016</b>			
Belt .....	421313		6831
<b>23-5350; 44-0300</b>			
Belt .....	107038		6836
<b>44-0334</b>			
Forward .....	107037		6831
Reverse .....	107039		6370
<b>44-0336</b>			
Forward .....	107038		6836
Reverse .....	107039		6370
<b>3029</b>			
Belt .....	107038		6836

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ATLAS - Continued</b>			
<b>3040</b>			
Forward .....	107038		6836
Reverse .....	107039		6370
<b>3042</b>			
Forward .....	107039		6370
Reverse .....	107039		6370
<b>3043</b>			
Belt .....	107038		6836
<b>3045</b>			
Forward .....	107039		6370
Reverse .....	107039		6370
<b>A17; A24</b>			
Belt .....	1072		6830
<b>A24R</b>			
Forward .....	1072		6830
Reverse .....	1073		6833
<b>ACC519; ACD919</b>			
Belt .....	107038		6836
<b>T17; T24</b>			
Belt .....	1072		6830
<b>T100; T100A</b>			
Belt .....	10712		6831
<b>T150</b>			
Forward .....	10712		6831
Reverse .....	10712		6831
<b>T200; T200A; T300; T300A</b>			
Belt .....	10712		6831
<b>T310</b>			
Belt .....	10735		6831
<b>T500</b>			
Belt .....	10712		6831
<b>T510; WT34</b>			
Belt .....	10735		6831
<b>AUTO HOE</b>			
<b>9E3-R; 34; 35; 36</b>			
Belt .....			6960
<b>AUTOMOTIVE ASSOCIATES</b>			
<b>212-100</b>			
Belt .....	7540103		6827
<b>212-255</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>212-355</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>212-370</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>213-100</b>			
Belt .....	7540103		6827
<b>213-255</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>213-360</b>			
Forward .....	7540166		6962
Reverse .....	7540146		6833
<b>213-375</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>214-100</b>			
Belt .....	7540103		6827
<b>214-255</b>			
Forward .....	7540107		6830

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>AUTOMOTIVE ASSOCIATES - Continued</b>			
<b>214-255 - Continued</b>			
Reverse .....	7540106		6825
<b>214-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>214-375</b>			
Forward .....	7540190		6839
Reverse .....	7540189		6844
<b>214-385</b>			
Belt .....	7540192		6834
<b>215-100</b>			
Belt .....	7540196		6830
<b>215-255</b>			
Forward .....	7540196		6830
Reverse .....	7540106		6825
<b>215-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>215-375</b>			
Forward .....	7540190		6839
Reverse .....	7540189		6844
<b>215-385</b>			
Belt .....	7540192		6834
<b>216-100</b>			
Belt .....	7540196		6830
<b>216-255</b>			
Forward .....	7540196		6830
Reverse .....	7540106		6825
<b>216-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>216-375</b>			
Forward .....	7540190		6839
Reverse .....	7540189		6844
<b>216-385</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>217-100</b>			
Belt .....	7540196		6830
<b>217-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>217-375</b>			
Forward .....	7540154		6837
Reverse .....	7540190		6839
<b>217-385</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>218-360</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>BLUE GRASS</b>			
<b>214-404</b>			
Forward .....	7540109		6843
Reverse .....	7540195		6854
<b>B310-4</b>			
Belt .....	7540190		6839
<b>BG156</b>			
Forward .....	9040B		6822
<b>BG381-4</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>BG385-4</b>			
Belt .....	7540192		6834

Lawn & Garden Equipment

**TILLERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BLUE GRASS - Continued</b>			
<b>BG401</b>			
Reverse .....	17139		6821
<b>BG560</b>			
Forward .....	7540154	6837	
Reverse .....	7540189	6844	
<b>BG601; BG701; BG805</b>			
Forward .....	9040B	6822	
Reverse .....	17139	6821	
<b>BG901H</b>			
Forward .....	15953	6833	
Reverse .....	15954	6834	
<b>W7-B102</b>			
Forward .....	7540196	6830	
<b>W7-BG320-D</b>			
Belt .....	7540190	6839	
<b>W7-BG355</b>			
Forward .....	7540154	6837	
Reverse .....	7540189	6844	
<b>W7-BG385-D; W7-BG387</b>			
Forward .....	7540154	6837	
Reverse .....	7540201	6841	
<b>BOLENS</b>			
<b>70-01</b>			
Belt .....	1706907	6824	
<b>2046-01</b>			
Drive .....	1108467	6834	
Reverse .....	1185487	6732	
<b>2048-01</b>			
Forward .....	1705034	6835	
Reverse .....	1185487	6732	
<b>2056-01</b>			
Belt; W/30" Belt O.C. ....	1712719	6730	
Belt; W/33" Belt O.C. ....	1800367	6833	
<b>2058-01</b>			
Forward .....	1705034	6835	
Reverse .....	1185487	6732	
<b>2064-01; 2064-02</b>			
Drive .....	1705034	6835	
<b>2066-01; 2067-01; 2068</b>			
Drive .....	1800367	6833	
Reverse .....	1185434	6737	
<b>2071-01; 2072-01; 2072-02</b>			
Belt .....	1706907	6824	
<b>2077-01; 2077-02</b>			
Belt .....	1108536	6927	
<b>2080-01</b>			
Belt .....	1707233	6826	
<b>2091-01; 2091-02</b>			
Drive .....	1800367	6833	
<b>2100-01</b>			
Belt; W/30" Belt O.C. ....	1712719	6730	
Belt; W/33" Belt O.C. ....	1800367	6833	
<b>2100-02; 2101-01; 2101-02; 2102-01; 2103-01;</b>			
<b>2104-01; 2104-02; 2150-01</b>			
Drive .....	1800367	6833	
Reverse .....		6731	
<b>2152</b>			
Belt .....	9304	6829	
<b>2162</b>			
Drive .....	200555	6746	
<b>2230</b>			
Belt .....		6843	
<b>2250</b>			
Belt .....		6743	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS - Continued</b>			
<b>2255</b>			
Drive .....	1800367		6833
Reverse .....			6731
<b>M16; M16A; M16B-01; M16D-01; MA16A01;</b>			
<b>MA16B01; MA16D01</b>			
Belt .....	1800367		6833
<b>BRINLY-HARDY</b>			
<b>BB-526</b>			
Belt .....	B2065		6833
<b>BM-15664</b>			
Drive .....	M43795		6841
<b>BM-15856</b>			
P.T.O. ....	M43820		6914BR
<b>V-223</b>			
Primary .....	V223		②6837
<b>VV-100</b>			
Drive .....	V131		6958
<b>VV-110</b>			
Primary .....	V223		②6837
<b>VV-200</b>			
Drive .....	V131		6958
<b>VV-210</b>			
Primary .....	V223		②6837
<b>VV-300</b>			
Drive .....	V131		6958
<b>VV-310</b>			
Primary .....	V223		②6837
<b>VV-330; VV-336</b>			
Drive .....	V393		6947
<b>BURNS</b>			
<b>11-279; 11-280; 11-294; 11-295; 11-296</b>			
Forward .....	9304		6829
<b>11-297; 11-298; 11-299; 199</b>			
Forward .....	9304		6829
Reverse .....	9308		6825
<b>275; 279; 280</b>			
Forward .....	9304		6829
<b>297; 299</b>			
Forward .....	9304		6829
Reverse .....	9308		6825
<b>5020</b>			
Forward .....	9304		6829
<b>5025</b>			
Forward .....	9304		6829
Reverse .....	9308		6825
<b>5030</b>			
Belt; W/26" Belt O.C. ....			6826
Belt; W/29" Belt O.C. ....			6829
<b>51034; 51035; 51116</b>			
Forward .....	9304		6829
<b>51138</b>			
Traction .....	208526		6738
<b>BP100</b>			
Belt .....			6820
<b>CANADA</b>			
<b>60-4023; 60-4023A5</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>60-4032</b>			
Drive .....	33622		6727

②Two Required





Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CANADA - Continued</b>				<b>COAST TO COAST - Continued</b>			
60-4034 Traction .....	200555		6746	10-340 Belt .....	1526		6822
40081 Forward .....	208301		6833	10-367; 10-372 Belt .....	3660		6825
Reverse .....	208626		6727	10-395 Belt .....	1526		6822
41077A Belt .....	208301		6833	10-459 Forward .....	1110		6835
51011Z Drive .....	9304		6829	Reverse .....	6163		6737
51075Z Drive .....	27093		6847	219-030 Belt .....	7540216		6729
51082Z Forward .....	1110		6835	313-7123 Forward .....	7540107		6830
Reverse .....	6163		6737	Reverse .....	7540106		6825
51102Z Drive .....	33622		6727	350 Belt .....	7540103		6827
51105Z Drive .....	36019		6720	481-1006 Forward .....	7540196		6830
51109Z Drive .....	9304		6829	Reverse .....	7540106		6825
51110Z Drive .....	36019		6720	481-1014 Forward .....	7540154		6837
51114Z; 51117; 51117Z; 51136Z Traction .....	200555		6746	Reverse .....	7540189		6844
500081 Belt .....	208301		6833	481-1220 Belt .....	7540216		6729
600081 Forward .....	208626		6727	481-1246 Belt .....	33622		6727
Reverse .....	208626		6727	481-1261 Forward .....	1110		6835
<b>CARTER BROS. MFG.</b>				Reverse .....	6163		6737
Rowbuster Drive .....	P904		6961	481-1279 Forward .....	2435		6837
<b>CHIEF</b>				Reverse .....			6739
1960-J Forward .....	1526		6822	481-1303 Forward .....	27093		6847
1960-JD Drive .....	1040		6832	481-1949 Forward .....	7540154		6837
<b>CHOREMASTER</b>				Reverse .....	7540189		6844
500391; 500410; 500516; 500618 Forward .....	511192	2330		481-1964 Forward .....	7540154		6837
Reverse .....	511193		6733	Reverse .....	7540201		6841
500733 Belt .....	516113		6833	481-1980 Drive .....	7540220		6927
Dub-L-Til Belt .....	511192		6833	Variable Speed .....	7540221		6952
Super Duty TU227100 Belt; W/17" Belt O.C. ....	J9004		6817	481-2400 Belt .....	7540196		6830
Belt; W/19" Belt O.C. ....			6819	481-2426 Forward .....	7540154		6837
Tiller Belt; W/32" Belt O.C. ....			6832	Reverse .....	7540189		6844
Belt; W/33" Belt O.C.; W/1/2" Belt T.W. ....	511192	2330		481-2430 Belt .....	7540190		6839
Belt; W/33" Belt O.C.; W/3/8" Belt T.W. ....	511193		6733	481-2442 Forward .....	7540154		6837
Belt; W/34" Belt O.C. ....	513381		6834	Reverse .....	7540201		6841
Belt; W/35" Belt O.C. ....	513465		6735	481-2467 Drive .....	7540224		6926
Belt; W/41" Belt O.C. ....	513857		6741	Variable Speed .....	7540221		6952
Til-O-Matic TU227200 Belt; W/17" Belt O.C. ....	J9004		6817	481-2475; 481-2483 Drive .....	7540220		6927
Belt; W/19" Belt O.C. ....			6819	Variable Speed .....	7540221		6952
<b>COAST TO COAST</b>				481-2491 Belt .....	7540216		6729
10-223; 10-224 Forward .....	1110		6835	481-4026 Belt .....	7540190		6839
Reverse .....	6163		6737				



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COAST TO COAST - Continued</b>			
<b>481-4059</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>481-4067</b>			
Forward .....	7540109		6843
Reverse .....	7540195		6854
<b>481-4091</b>			
Tine .....	7540268		6951
<b>481-6091</b>			
Forward .....	7540220		6927
Reverse .....	7540268		6951
<b>500</b>			
Forward .....	7540177		6832
Reverse .....	7540146		6833
<b>800</b>			
Forward .....	7540154		6837
<b>HEO844; HEO846; HEO854; HEO857</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>HEO863; HEO864</b>			
Belt .....	3660		6825
<b>HEO875; HEO877; HEO879</b>			
Belt .....	1526		6822
<b>HEO889; HEO890</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>Plow Horse 212-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>Plow Horse 212-355</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>Plow Horse 212-370</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>Plow Horse 213-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>Plow Horse 213-355</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>Plow Horse 213-375</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>Plow Horse 214-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>Plow Horse 214-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>Plow Horse 214-375</b>			
Forward .....	7540190		6839
Reverse .....	7540189		6844
<b>Plow Horse 214-385</b>			
Tine .....	7540192		6834
<b>Plow Horse 215-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>COLUMBIA PRODUCTS</b>			
<b>200-3; 200-4; 210-200; 210-250</b>			
Forward .....	7540106		6825
Reverse .....	7540107		6830
<b>210-350; 210-360</b>			
Belt .....	7540104		6832

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COLUMBIA PRODUCTS - Continued</b>			
<b>211-200; 211-255</b>			
Forward .....	7540106		6825
Reverse .....	7540107		6830
<b>211-355; 211-360</b>			
Belt .....	7540104		6832
<b>212-030</b>			
Belt .....	7540216		6729
<b>212-200</b>			
Forward .....	7540106		6825
Reverse .....	7540107		6830
<b>212-300</b>			
Belt .....	7540190		6839
<b>212-355</b>			
Belt; W/37" Belt O.C. ....	7540154		6837
Belt; W/44" Belt O.C. ....	7540189		6844
<b>212-375</b>			
Belt; W/39" Belt O.C. ....	7540190		6839
Belt; W/44" Belt O.C. ....	7540189		6844
<b>212-381</b>			
Belt; W/37" Belt O.C. ....	7540154		6837
Belt; W/41" Belt O.C. ....	7540201		6841
<b>212-386</b>			
Belt; W/19" Belt O.C. ....	7540254		6819
Belt; W/29" Belt O.C. ....	7540265		6829
<b>212-410</b>			
Belt; W/26" Belt O.C. ....	7540224		6926
Belt; W/51" Belt O.C. ....	7540268		6951
<b>212-412</b>			
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/51" Belt O.C. ....	7540268		6951
<b>355-4</b>			
Belt; W/37" Belt O.C. ....	7540154		6837
Belt; W/44" Belt O.C. ....	7540189		6844
<b>357-3</b>			
Forward .....	7540177		6832
Reverse .....	7540146		6833
<b>357-4</b>			
Belt; W/37" Belt O.C. ....	7540154		6837
Belt; W/44" Belt O.C. ....	7540189		6844
<b>381-3</b>			
Belt .....	7540158		6935
<b>382-4; 385-4</b>			
Belt .....	7540192		6834
<b>389-3; 395-4</b>			
Belt .....	7540158		6935
<b>COTTER &amp; CO.</b>			
<b>10-546-22; 440; 441</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>442</b>			
Belt .....	1526		6822
<b>443</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>840</b>			
Belt .....	1526		6822
<b>51028</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51029</b>			
Belt .....	1526		6822
<b>51030</b>			
Forward .....	2435		6837
Reverse .....			6739



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>COTTER &amp; CO. - Continued</b>			
<b>GTR5</b>			
Tine .....	7540195		6854
Variable Speed .....	7540109		6843
<b>CRUSADER</b>			
<b>218-250</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>218-350; 218-360</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>CUB CADET</b>			
<b>030</b>			
Drive; W/3 H.P. Eng. ....	7540216		6729
<b>381</b>			
Drive; W/37" Belt O.C.; W/5 H.P. Eng. ....	7540154		6837
Drive; W/41" Belt O.C.; W/5 H.P. Eng. ....	7540201		6841
<b>FT 24; FT 24 R</b>		2420	
Forward .....	9540428		6746
Reverse .....	9540429		
<b>RT 35</b>			
Forward .....	954-04090		6825
<b>RT 45</b>			
Forward .....	954-04090		6825
Reverse .....	954-04091		6610BR
<b>RT 65; RT 65ES</b>			
Drive .....	9540434		6858
<b>RT 75</b>			
Forward .....	954-04090		6825
Reverse .....	954-04091		6610BR
<b>DAVIS</b>			
<b>144; 144C; 145; 145C; 391; 392; 393</b>			
Forward .....	4052		6855
Reverse; W/4 H.P. Eng. ....	4051		6731
<b>DILLE &amp; MCGUIRE</b>			
<b>2946; 2947</b>			
Forward .....	BE115		6820
Reverse .....	BE119		6821
<b>H14; HA14; HB14</b>			
Belt .....	BE111		6833
<b>TA14</b>			
Belt .....	BE115		6820
<b>TB14</b>			
Forward .....	BE116		6822
Reverse .....	BE119		6821
<b>TT12; TT14</b>			
Belt .....	BE111		6833
<b>V14; VA14; VB14; VC14</b>			
Forward .....	BE116		6822
Reverse .....	BE115		6820
<b>DURITE</b>			
<b>MTH3</b>			
Belt; W/37" Belt O.C. ....	2370		6837
Forward; W/35" Belt O.C. ....	2350		6835
<b>MTH3R</b>			
Belt; W/37" Belt O.C. ....	2370		6837
Forward; W/35" Belt O.C. ....	2350		6835
Reverse .....	1310		6731
<b>MTH4</b>			
Belt; W/37" Belt O.C. ....	2370		6837
Forward; W/35" Belt O.C. ....	2350		6835
<b>MTH4R</b>			
Belt; W/37" Belt O.C. ....	2370		6837
Forward; W/35" Belt O.C. ....	2350		6835

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DURITE - Continued</b>			
<b>MTH4R - Continued</b>			
Reverse .....	1310		6731
<b>MTH5</b>			
Belt; W/37" Belt O.C. ....	2370		6837
Forward; W/35" Belt O.C. ....	2350		6835
<b>MTH5R</b>			
Belt; W/37" Belt O.C. ....	2370		6837
Forward; W/35" Belt O.C. ....	2350		6835
Reverse .....	1310		6731
<b>DYNAMARK</b>			
<b>1334-00; 1334-03; 1334-04</b>			
Belt; W/26" Belt O.C. ....	21865		6826
Belt; W/43" Belt O.C. ....	45216		6843
<b>1336-01; 1336-02; 1336-03</b>			
Forward .....	45216		6843
Reverse .....	45217		6839
<b>1340-00; 1344-01; 1344-02; 1345-00; 1345-01; 1345-02; 1346-01; 1346-02; 1346-03; 1346-05</b>			
Belt .....	21865		6826
<b>1346-06; 1346-07; 1346-09; 1346-10; 1346-11; 1346-12; 1346-13; 1346-14; 1347-00; 1347-02</b>			
Belt .....	21865		6826
<b>1347-03; 1347-04</b>			
Belt .....	21865		6826
<b>1348-00; 1348-02; 1348-03; 1348-05; 1349-00; 1349-01; 1349-02; 1349-03; 1349-05; 1349-06</b>			
Forward .....	32131		6838
Reverse .....	32132		6839
<b>1349-07; 1349-08; 1349-09; 1349-10; 1349-11</b>			
Forward .....	32131		6838
Reverse .....	32132		6839
<b>1460-00</b>			
Belt .....	8271		6827
<b>2805-12</b>			
Drive; W/5 H.P. Eng. ....	50876		6738
<b>5300-00</b>			
Belt .....	8271		6827
<b>5333-00; 5333-01</b>			
Belt .....	50877		6741
<b>5334-00; 5334-06; 5335-00; 5335-01; 5335-02; 5336-04; 5336-05</b>			
Belt .....	45216		6843
<b>5336-06</b>			
Reverse .....	45217		6839
<b>5336-08</b>			
Belt .....	45216		6843
<b>5336-09</b>			
Reverse .....	45217		6839
<b>5343-00; 5343-01; 5343-30; 5343-35; 5343-39; 5343-40; 5344-00; 5344-35; 5345-00; 5345-01</b>			
Belt .....	21865		6826
<b>5345-02; 5345-03; 5345-30; 5345-32; 5345-33; 5345-35; 5345-36; 5345-38; 5345-43; 5345-45</b>			
Belt .....	21865		6826
<b>5345-46; 5345-47; 5345-49; 5345-50; 5345-51; 5345-53; 5346-00; 5346-01; 5346-02; 5346-03</b>			
Belt .....	21865		6826
<b>5346-04; 5346-05; 5346-06; 5346-07; 5346-08; 5346-11; 5346-12; 5346-14; 5346-30; 5346-40</b>			
Belt .....	21865		6826
<b>5346-42; 5346-44; 5346-46; 5346-50; 5346-51; 5347-00; 5347-01; 5347-02; 5347-04; 5347-30</b>			
Belt .....	21865		6826

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
5347-31; 5347-33; 5347-34; 5347-37; 5347-40; 5347-42; 5347-44; 5347-45; 5347-46; 5347-47 Belt .....	21865		6826
5347-48; 5347-49; 5347-50; 5347-51; 5347-52; 5347-53; 5347-54; 5347-55; 5347-56; 5347-57 Belt .....	21865		6826
5347-58 Belt .....	21865		6826
5348-00; 5348-01; 5348-02; 5348-05; 5349-00; 5349-01; 5349-02; 5349-04; 5349-05; 5349-06 Forward .....	32131		6838
Reverse .....	32132		6839
5349-07; 5349-08; 5349-33; 5349-35; 5349-38; 5349-40; 5349-41; 5349-42; 5349-43 Forward .....	32131		6838
Reverse .....	32132		6839
<b>5359-1000</b>			
Auger; W/28" Belt O.C. ....			6728
Auger; W/37" Belt O.C. ....	49570		6837
<b>5361-20; 5361-22; 5361-24</b>			
Drive .....			6837
<b>50401-1; 50401-3; 50404; 50406; 50407-1; 50407-3; 50409-4; 50409-5; 50414; 50416</b>			
Belt .....	28148		6826
<b>50417-1; 50417-3; 50417-4; 50417-5; 50417-6</b>			
Belt .....	28148		6826
<b>50429-4; 50429-6</b>			
Forward .....	32131		6838
Reverse .....	32132		6839
<b>901011; 901012; 901016</b>			
Forward .....	72119		6830
Reverse .....	72106		6737
<b>901017</b>			
Forward .....	72046		6731
Reverse .....	72106		6737
<b>901018</b>			
Forward .....	72126		6736
Reverse .....	72127		6741
<b>RT300; RT500</b>			
Belt .....	8271		6827
<b>EARTHQUAKE</b>			
<b>5 H.P.; 8 H.P.</b>			
Tine .....			6831
<b>EDKO</b>			
<b>Eddy Boy; Till-Master; Till-Trac</b>			
Belt .....	20560		6850
<b>EJ SMITH</b>			
<b>11-277-21</b>			
Forward .....	9304		6829
Reverse .....	9308		6825
<b>11-282-21</b>			
Drive .....	9304		6829
<b>197</b>			
Forward .....	9304		6829
Reverse .....	9308		6825
<b>198</b>			
Drive; W/4 H.P. Eng.; W/O Reverse .....	9304		6829
Drive; W/Reverse .....	9304		6829
Reverse .....	9308		6825
<b>282</b>			
Drive .....	9304		6829

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FALLS</b>			
2300; 2305; 2320; BRT23-100; CPRT23-100; G23-102; T-7 Drive .....	T7163		6835
<b>FELDMANN</b>			
<b>35-SR</b>			
Belt; W/B. & S. 3 1/2 H.P. Eng.; W/24" Belt O.C. ....	1320		6824
Belt; W/B. & S. 3 1/2 H.P. Eng.; W/26" Belt O.C. ....	S78		6826
Belt; W/B. & S. 3 1/2 H.P. Eng.; W/28" Belt O.C. ....			6828
Belt; W/Tecumseh 3 1/2 H.P. Eng. ....	S79		6828
<b>52-SR</b>			
Belt; W/B. & S. 5 H.P. Eng. ....	T55		6833
Belt; W/Tecumseh 5 H.P. Eng. ....	T54		6820
<b>63147</b>			
Drive .....	1371		6828
Reverse .....	1597		6725
<b>65000; 65158; 65259</b>			
Drive .....	1371		6828
Reverse .....	1384		6826
<b>72335; 72335B; 83335; 83355</b>			
Belt .....	1434		6728
<b>Jiffy 35S</b>			
Drive .....			6828
<b>Jiffy 35SR</b>			
Forward .....			6828
Reverse .....			6825
<b>Jiffy 45S; Jiffy 51S</b>			
Drive .....			6828
<b>Jiffy 52SR</b>			
Forward .....	1235		6833
Reverse .....	1234		6820
<b>Jiffy 61S</b>			
Drive .....			6828
<b>FIRESTONE</b>			
<b>08-08-303-7</b>			
Drive .....	7540103		6827
<b>08-08-500-5</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>08-08-501-3</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>08-08-502-1</b>			
Trans. ....	7540158		6935
<b>08-08-504-8</b>			
Tine .....	7540192		6834
<b>08-08-550-1</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>422-3-100</b>			
Drive .....	7540103		6827
<b>422-3-255</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>422-3-360</b>			
Forward .....	7540166		6962
Reverse .....	7540146		6833
<b>422-5-100</b>			
Belt .....	7540196		6830
<b>422-5-360</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FIRESTONE - Continued</b>			
<b>422-5-375</b>			
Forward .....	7540190		6839
Reverse .....	7540189		6844
<b>422-5-385</b>			
Tine .....	7540192		6834
<b>422-5-525</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>Supreme 08-08-500-5</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>FLO-MOW</b>			
<b>Flow-Mow 24</b>			
Forward .....			6837
Reverse .....			6731
<b>MIT-4</b>			
Forward .....			6835
<b>MIT-5</b>			
Forward .....			6837
Reverse .....			6731
<b>MIT-6</b>			
Forward .....			6838
Reverse .....			6731
<b>FORD</b>			
<b>09GN-1005</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>09GN-1013</b>			
Belt .....	9304		6829
<b>09GN-1023</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>09GN-1105</b>			
Belt .....	36019		6720
<b>09GN-1114</b>			
Traction .....	200555		6746
<b>09GN-1182</b>			
Traction .....	240684		6746
<b>09GN-1183</b>			
Traction .....	234594		6950
<b>09GN-3639; 09GN-3672; 09GN-3695</b>			
Secondary .....			6840
<b>9607425</b>			
Traction .....	234594		6950
<b>9607426</b>			
Traction .....	240684		6746
<b>9607447</b>			
Secondary .....			6840
<b>RT5</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>RTC5</b>			
Traction .....	382069304		6829
<b>GAMBLE SKOGMO</b>			
<b>37-6042</b>			
Reverse .....	511193		6733
<b>210-405A</b>			
Drive .....	7540224		6926
Variable Speed .....	7540221		6952
<b>210-408A; 210-409A</b>			
Drive .....	7540221		6952
Variable Speed .....	7540220		6927

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GAMBLE SKOGMO - Continued</b>			
<b>214-310</b>			
Belt .....	7540190		6839
<b>219-380A</b>			
Forward .....	7540154		6837
<b>219-385A</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>219-405A</b>			
Drive .....	7540224		6926
Variable Speed .....	7540221		6952
<b>219-408A</b>			
Drive .....	7540221		6952
Variable Speed .....	7540220		6927
<b>556</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>6020A</b>			
Reverse .....	51193		6733
<b>6051A; 6051B</b>			
Drive .....	7540154		6837
Reverse .....	7540155		6509BR
<b>9077A</b>			
Belt .....	7540103		6827
<b>9081A</b>			
Reverse .....	64T34		6731
<b>9082A; 9082B; 9083A; 9083B; 9083C; 9083D</b>			
Drive .....	7540104		6832
Reverse .....	7540103		6827
<b>9083E</b>			
Drive .....	7540121		6831
Reverse .....	7540146		6833
<b>9084A; 9084B; 9084C</b>			
Drive .....	7540106		6825
Reverse .....	7540107		6830
<b>9088A</b>			
Reverse .....			6739
<b>50014</b>			
Forward .....	511192	2330	6833
Reverse .....	511193		6733
<b>500270</b>			
Belt .....	515332		6826
<b>500426; 500427</b>			
Forward .....	511192	2330	6833
Reverse .....	511193		6733
<b>FS42-6051A; FS42-6051B; FS42-6081B</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>FS42-6110B</b>			
Belt .....	7540158		6935
<b>FS59-6019-6B; FS59-6019-6C; FS59-6019-6D; FS59-6020-A; FS59-6020-B; FS59-6020-C; FS59-6035-A</b>			
Forward .....	511192	2330	6833
Reverse .....	511193		6733
<b>FS59-6035-C</b>			
Reverse .....	511193		6733
<b>FS59-6060-A; FS59-6060-C</b>			
Reverse .....	513465		6735
<b>FS59-6105-A; FS59-6105-C</b>			
Forward .....	513381		6834
Reverse .....	513465		6735
<b>FS59-6106-1A</b>			
Forward .....	516113		6833
Reverse .....	516114	1275	

Lawn & Garden Equipment



TILLERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GAMBLE SKOGMO - Continued</b>			
FS59-6106-C			
Forward .....	516113		6833
Reverse .....	516747		6727
FS59-6179-A			
Forward .....	516113		6833
FS59-61038-A			
Belt .....	515332		6826
<b>GARDEN STAR</b>			
8030D			
Belt .....	6833		6013
<b>GILSON</b>			
10-120-09			
Belt .....	1110		6835
10-150-06I; 10-152-06; 10-153-09; 10-154-06			
Belt .....	3114		6817
10-200-01C; 10-201-02V; 10-202-02D; 10-204-05DA; 10-205-01C; 10-206-02D; 10-207-02V; 10-208-05DA; 10-209-09V; 10-211-02			
Belt .....	1110		6835
10-212-01; 10-213-02; 10-214-02; 10-215-02; 10-216-05; 10-217-09; 10-218-10; 10-219-10; 10-220-02			
Belt .....	1110		6835
10-222-01; 10-222-02			
Forward .....	1110		6835
Reverse .....	6163		6737
10-225-03			
Belt .....	1110		6835
10-228-05; 10-229-03			
Forward .....	1110		6835
Reverse .....	6163		6737
10-230-03			
Forward .....	2435		6837
Reverse .....			6739
10-231-04; 10-232-05			
Forward .....	1110		6835
Reverse .....	6163		6737
10-233-05			
Forward .....	2435		6837
Reverse .....			6739
10-234-04; 10-235-04; 10-236-01; 10-237-01; 10-238-02; 10-239-02			
Forward .....	1110		6835
Reverse .....	6163		6737
10-240-03			
Forward .....	7740		6838
Reverse .....	7838		6734
10-241-05			
Forward .....	1110		6835
Reverse .....	6163		6737
10-242-05			
Forward .....	2435		6837
Reverse .....			6739
10-243-01; 10-244-12; 10-245-01			
Forward .....	1110		6835
Reverse .....	6163		6737
10-246-03			
Forward .....	2435		6837
Reverse .....			6739
10-247-03; 10-248-04; 10-249-10			
Forward .....	1110		6835
Reverse .....	6163		6737

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
10-252-01; 10-253-02			
Belt .....	4052		6855
10-254-01; 10-255-02; 10-256-01; 10-257-02			
Forward .....	4052		6855
Reverse .....	4051		6731
10-259-02; 10-260-01			
Belt .....	4052		6855
10-261-01; 10-262-01; 10-262-02; 10-263-05; 10-264-05; 10-265-01; 10-266-01; 10-270-05; 10-271-03; 10-285-05			
Forward .....	4052		6855
Reverse .....	4051		6731
10-300-01S; 10-301-07SM; 10-302-03; 10-303-02J; 10-305-01S; 10-306-02J; 10-307-07; 10-309-03; 10-310-03; 10-313-02			
Belt .....	1526		6822
10-317-01; 10-318-02; 10-320-04; 10-321-04; 10-323-01; 10-324-01; 10-325-02; 10-326-02; 10-327-03; 10-328-06			
Belt .....	1526		6822
10-329-04; 10-330-04; 10-331-01; 10-332-01; 10-333-06; 10-334-02; 10-335-02; 10-336-01; 10-337-01; 10-341-10			
Belt .....	1526		6822
10-342-23; 10-344-03; 10-345-04; 10-346-04; 10-347-01; 10-349-01			
Belt .....	1526		6822
10-350-04			
Belt .....	3660		6825
10-351-03; 10-352-01			
Belt .....	3866		6826
10-353-01; 10-354-02; 10-355-03			
Belt .....	3660		6825
10-357-05			
Belt .....	3866		6826
10-358-12; 10-360-03; 10-361-02; 10-361-06; 10-361-22; 10-362-01; 10-364-02; 10-366-04			
Belt .....	3660		6825
10-366-05			
Belt .....	3866		6826
10-368-01; 10-369-02			
Belt .....	3660		6825
10-370-05			
Forward .....	1110		6835
Reverse .....	6163		6737
10-371-01; 10-374-01; 10-375-01; 10-375-06; 10-376-02; 10-377-01			
Belt .....	3660		6825
10-396-22; 10-397-03; 10-398-06; 10-399-01			
Belt .....	1526		6822
10-400-01SD; 10-401-03; 10-402-03; 10-403-10V; 10-404-02JD; 10-405-02; 10-406-01SD; 10-407-02JD; 10-408-01; 10-409-03			
Belt .....	1040		6832
10-410-06; 10-411-06; 10-412-06; 10-413-06; 10-414-03; 10-415-06; 10-416A-03; 10-416B-03; 10-417A-03; 10-417B-03			
Belt .....	1040		6832
10-450-04; 10-451-01; 10-452-02; 10-453-04; 10-454-01; 10-455-05; 10-456-05			
Forward .....	1110		6835
Reverse .....	6163		6737



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
10-457-05; 10-458-05; 10-461-05			
Forward .....	2435		6837
Reverse .....			6739
10-502-09UR; 10-503-05; 10-504-11UA; 10-505-12U; 10-506-09; 10-507-07; 10-508-06; 10-509-06V; 10-512-05; 10-515-01			
Belt .....	1110		6835
10-516-02; 10-522-05; 10-523-05; 10-524-09; 10-525-06			
Belt .....	1110		6835
10-530-02; 10-531-06; 10-532-06; 10-532-22; 10-532A-06; 10-533-03; 10-534-05; 10-536-06; 10-536-10; 10-537-04			
Forward .....	1110		6835
Reverse .....	6163		6737
10-538-01; 10-539-05; 10-540-02; 10-541-01; 10-543-10; 10-545-25; 10-554-01			
Forward .....	1110		6835
Reverse .....	6163		6737
11-276-26			
Belt .....	9304		6829
11-277-21			
Forward .....	9304		6829
Reverse .....	9308		6825
11-278-15; 11-281-21; 11-282-21; 11-284-19; 11-285-18; 11-286-17; 11-287-16; 11-288-15; 11-289-15; 11-290-15			
Belt .....	9304		6829
11-291-15; 11-292-15; 11-293-15; 11-297; 11-298; 11-299			
Forward .....	9304		6829
Reverse .....	9308		6825
44-0315			
Forward .....	1110		6835
Reverse .....	6163		6737
44-0318; 44-0462; 44-0463; 44-0464; 44-0465			
Forward .....	2435		6837
Reverse .....			6739
60-4023; 60-4023-A5			
Forward .....	1110		6835
Reverse .....	6163		6737
94-2060-5			
Belt .....	9304		6829
151			
Belt .....	3114		6817
198; 199			
Forward .....	9304		6829
Reverse .....	9308		6825
227			
Belt .....	1110		6835
242			
Forward .....	1110		6835
Reverse .....	6163		6737
268; 269			
Forward .....	4052		6855
Reverse .....	4051		6731
272; 273			
Forward .....	1110		6835
Reverse .....	6163		6737
274			
Forward .....	4052		6855
Reverse .....	4051		6731
276			
Belt .....	9304		6829

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
277			
Forward .....	9304		6829
Reverse .....	9308		6825
281; 282; 284; 285; 286			
Belt .....	9304		6829
300			
Forward .....	1110		6835
Reverse .....	6163		6737
311; 312; 314; 315; 316; 322; 339; 343; 348			
Belt .....	1526		6822
363; 378; 379			
Belt .....	3660		6825
381; 382			
Belt .....	1526		6822
393			
Forward .....	4052		6855
Reverse .....	4051		6731
394			
Belt .....	1526		6822
442; 454; 500			
Forward .....	1110		6835
Reverse .....	6163		6737
519; 520; 521; 528			
Belt .....	1110		6835
547; 550; 551-42304; 551-42382; 551-42475			
Forward .....	1110		6835
Reverse .....	6163		6737
552			
Forward .....	2435		6837
Reverse .....			6739
553			
Forward .....	1110		6835
Reverse .....	6163		6737
554			
Forward .....	2435		6837
Reverse .....			6739
557; 558; 2025-A47; 2025-A57; 2025-A67; 2025-A77; 2025-B57			
Forward .....	1110		6835
Reverse .....	6163		6737
6290			
Forward .....	2435		6837
Reverse .....			6739
6457-05			
Forward .....	4052		6855
Reverse .....	4051		6731
6548-4; 6548-5			
Forward .....	1110		6835
Reverse .....	6163		6737
6552-4			
Belt .....	3866		6826
6650-4; 6650-5			
Forward .....	2435		6837
Reverse .....			6739
6652-5			
Forward .....	1110		6835
Reverse .....	6163		6737
6680; 6682-4; 6683-5			
Forward .....	4052		6855
Reverse .....	4051		6731
6750-6; 6751-6			
Forward .....	1110		6835
Reverse .....	6163		6737
6752-6; 6753-6			
Forward .....	2435		6837

Lawn & Garden Equipment

**TILLERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
<b>6752-6; 6753-6 - Continued</b>			
Reverse .....			6739
<b>6754-6</b>			
Forward .....	4052		6855
Reverse .....	4051		6731
<b>6800</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>6801</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>6802</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>6803</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>6804</b>			
Forward .....	4052		6855
Reverse .....	4051		6731
<b>6809; 6810</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>6811</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>39007A; 50147</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51001</b>			
Belt .....	1526		6822
<b>51002; 51003</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51004</b>			
Belt .....	3660		6825
<b>51005</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>51006</b>			
Belt .....	1526		6822
<b>51007; 51008</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51009</b>			
Belt .....	3660		6825
<b>51010</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>51011; 51012; 51013</b>			
Belt .....	9304		6829
<b>51016</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51017</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>51018</b>			
Belt .....	1526		6822
<b>51019; 51020</b>			
Forward .....	4052		6855
Reverse .....	4051		6731
<b>51021; 51022; 51023; 51025</b>			
Forward .....	1110		6835
Reverse .....	6163		6737

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
<b>51031</b>			
Belt .....	1526		6822
<b>51034; 51035</b>			
Belt .....	9304		6829
<b>51040; 51041</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51049</b>			
Belt .....	1526		6822
<b>51050; 51051</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51052</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>51053</b>			
Belt .....	9304		6829
<b>51054</b>			
Belt .....	1526		6822
<b>51055</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51056; 51057; 51058; 51060</b>			
Belt .....	9304		6829
<b>51064</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51065</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>51073; 51074; 51075</b>			
Belt .....	27093		6847
<b>51076</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51077</b>			
Belt .....	3660		6825
<b>51078</b>			
Belt .....	1526		6822
<b>51079</b>			
Belt .....	3660		6825
<b>51080</b>			
Belt .....	26873		A65
<b>51082</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51083</b>			
Lower Drive .....	26345		6830
Upper Drive .....	26344		6819
<b>51084</b>			
Belt .....	1526		6822
<b>51085</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>51087; 51088</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51089</b>			
Belt .....	9304		6829
<b>51090; 51092</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51093</b>			
Belt .....	9304		6829



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
<b>51097; 51098</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51100</b>			
Belt .....	27093		6847
<b>51101</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51105</b>			
Belt .....	36019		6720
<b>51109</b>			
Belt .....	9304		6829
<b>51110</b>			
Belt .....	36019		6720
<b>51111</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51112</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>51113</b>			
Belt .....	26873		A65
<b>51116</b>			
Belt .....	9304		6829
<b>51119; 51121</b>			
Belt .....	3114		6817
<b>51122</b>			
Belt .....	1526		6822
<b>51125</b>			
Belt .....	36019		6720
<b>51126</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51127</b>			
Belt .....	27093		6847
<b>51135</b>			
Forward .....	208526		6738
Reverse .....	208525		6725
Tine .....	208527		6848
<b>51138</b>			
Forward .....	208301		6833
<b>51140</b>			
Forward .....	208526		6738
Reverse .....	208525		6725
Tine .....	208527		6848
<b>51142</b>			
Forward .....	208301		6833
<b>51143</b>			
Forward .....	208301		6833
Reverse .....	208626		6727
<b>151134</b>			
Forward .....	200554		6846
Reverse .....	200555		6746
<b>2029978</b>			
Belt .....	9304		6829
<b>15265150</b>			
Belt .....			6839
<b>GRAINGER, W. W.</b>			
<b>3Z469</b>			
Belt .....	7540103		6827
<b>3Z469B</b>			
Forward .....	7540196		6830
Reverse .....	7540106		6825

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAINGER, W. W. - Continued</b>			
<b>3Z469C</b>			
Belt .....	7540196		6830
<b>3Z470</b>			
Belt .....	7540166		6962
<b>3Z470A; 3Z470B; 3Z470C; 3Z470D</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>3Z471</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>3Z471A; 3Z471B</b>			
Forward .....	7540190		6839
Reverse .....	7540189		6844
<b>3Z502A</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>3Z502C</b>			
Belt .....	7540190		6839
<b>3Z642; 3Z642A; 3Z642C</b>			
Drive .....	7540216		6729
<b>3Z643; 3Z643A</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>3Z644</b>			
Drive .....	7540233		6821
Variable Speed .....	7540231		6828
<b>3Z885A</b>			
Belt; W/43" Belt O.C. ....	7540109		6843
Belt; W/54" Belt O.C. ....	7540195		6854
<b>31295</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>32309</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>51032</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>51033</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>HABAN</b>			
<b>Power Trac V</b>			
Forward .....	10467		6852
Reverse .....	10371		6843
<b>HAHN ECLIPSE</b>			
<b>7801; 7802; 7803</b>			
Forward .....	1362P		6720
Reverse .....	1362P		6720
<b>7804; 7810; 7901; 7902; 7903</b>			
Forward .....	308500		6720
Reverse .....	308500		6720
<b>8000; 8001</b>			
Forward .....	1362P		6720
Reverse .....	1206P		6719
<b>8004; 8005; 8006; 8007</b>			
Forward .....	1362P		6720
Reverse .....	1362P		6720
<b>8200; 8250; 8251</b>			
Forward .....	1362P		6720
Reverse .....	1206P		6719
<b>8252; 8253; 8254; 8256; 8257; 8258</b>			
Forward .....	1362P		6720
Reverse .....	1362P		6720

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HAWN ECLIPSE - Continued</b>			
8259; 8260; 8261; 8262; 8263; 8264; 8265			
Forward .....	308439		6833
Reverse .....	308447		6832
8400; 8401; 8402			
Forward .....	1362P		6720
Reverse .....	1206P		6719
8602; 8622			
Forward .....	308439		6833
Reverse .....	308440		6831
8650; 8651; 8652			
Forward .....	1362P		6720
Reverse .....	1206P		6719
8654; 8655; 8656; 8659; 8660; 8661			
Forward .....	1362P		6720
Reverse .....	1362P		6720
8663; 8664; 8665; 8666; 8667; 8668			
Forward .....	308439		6833
Reverse .....	308440		6831
8670; 8671; 8672			
Forward .....	1362P		6720
Reverse .....	1362P		6720
8674; 8675; 8677			
Forward .....	308500		6720
Reverse .....	308500		6720
<b>HANNIBAL MOWER</b>			
Tom Boy H-66-TR			
Forward .....			6836
Reverse .....			6835
Tom Boy H-713-1			
Drive .....			6835
Tom Boy H-715-R			
Forward .....			6836
Reverse .....			6835
Tom Boy H-715R-1			
Drive .....			6835
Reverse .....			6835
<b>HARDWARE WHOLESALERS, INC.</b>			
211-360; 212-355; 213-360			
Forward .....	7540121		6831
Reverse .....	7540146		6833
214-200			
Forward .....	7540107		6830
Reverse .....	7540106		6825
214-310			
Belt .....	7540190		6839
214-360			
Forward .....	7540154		6837
Reverse .....	7540189		6844
214-381			
Forward .....	7540154		6837
Reverse .....	7540201		6841
214-404			
Forward .....	7540109		6843
Reverse .....	7540195		6854
215-200			
Forward .....	7540196		6830
Reverse .....	7540106		6825
215-385			
Belt .....	7540192		6834
216-200			
Forward .....	7540196		6830
Reverse .....	7540106		6825
216-380; 216-385			
Forward .....	7540154		6837
Reverse .....	7540201		6841

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HARDWARE WHOLESALERS, INC. - Continued</b>			
217-020; 217-030			
Belt .....	7540216		6729
217-200			
Forward .....	7540196		6830
Reverse .....	7540106		6825
217-385			
Forward .....	7540154		6837
Reverse .....	7540201		6841
218-350; 218-360			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>HOMELITE</b>			
51086			
Drive .....	9304		6829
R3			
Forward .....	174883		6834
R4C			
Drive .....	9304		6829
R5			
Forward .....	174883		6834
Reverse .....	118494		6734
R8			
Forward .....	176393		6737
Reverse .....	176917		6837
<b>HOMKO</b>			
13440000; 13440100; 13450002; 13450200; 13460000; 13460200; 13460300; 13470100; 13470200; 13470300			
Drive .....	21865		6826
13480000; 13480200; 13490000; 13490100; 13490200			
Forward .....	32132		6839
Reverse .....	32131		6838
53433900; 53450300; 53460000; 53460100; 53460200; 53460300			
Drive .....	21865		6826
53463700			
Drive .....	28148		6826
53464000; 53464400			
Drive .....	21865		6826
53470000; 53470100			
Drive .....	28148		6826
53470200			
Drive .....	21865		6826
53473000; 53473100			
Drive .....	28148		6826
53480000; 53490000			
Forward .....	32132		6839
Reverse .....	32131		6838
<b>HONDA</b>			
F400 Series			
Drive .....	047765		6936
F401K2A; F401K2A2			
Drive .....	22431733622		6938
F500 Series			
Drive .....	047765		6936
F501K2A1; F501K2A2			
Drive .....	22431733752		6939
FG400A; FG500A			
Drive .....	22431727013		6939





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HONDA - Continued</b>			
<b>FR500</b>			
Belt .....	106375		6933
<b>FR600A; FR650A</b>			
Drive .....	22431734013		6941
<b>FR700</b>			
Belt .....	103647		6936
<b>FR750A</b>			
Drive .....	22431777731		6939
<b>FR800A</b>			
Drive .....	22431770700		6945
<b>HUFFMAN</b>			
<b>0948</b>			
Forward .....	9040B		6822
Reverse .....	17139		6821
<b>0949</b>			
Forward .....	15954		6834
Reverse .....	15953		6833
<b>2946</b>			
Forward .....	BE116		6822
Reverse .....	BE115		6820
<b>2947</b>			
Forward .....	BE116		6822
Reverse .....	BE119		6821
<b>2948</b>			
Forward .....	9040B		6822
Reverse .....	17139		6821
<b>2949</b>			
Forward .....	15954		6834
Reverse .....	15953		6833
<b>4946</b>			
Forward .....	BE116		6822
Reverse .....	BE115		6820
<b>4947</b>			
Forward .....	BE116		6822
Reverse .....	BE119		6821
<b>4948</b>			
Forward .....	9040B		6822
Reverse .....	17139		6821
<b>4949</b>			
Forward .....	15954		6834
Reverse .....	15953		6833
<b>HUSQVARNA</b>			
<b>550CRTH; 600CRT</b>			
Drive .....	532132801		6639BR
<b>CRT35</b>			
Drive .....	532132672		6853
<b>CRT52</b>			
Drive; W/52" Belt O.C. ....	532132801		6639BR
Drive; W/53" Belt O.C. ....	532132672		6853
<b>CRT61</b>			
Drive .....	532132801		6639BR
<b>CRT83</b>			
Drive .....	532138399		6859
<b>INTERNATIONAL</b>			
<b>526</b>			
Belt; W/40" Belt O.C. ....	59004C1		6840
Belt; W/45" Belt O.C. ....	59003C1		6845
<b>JACOBSEN</b>			
<b>52200</b>			
Drive .....	313582		6925
<b>52210</b>			
Drive .....	314564		6829

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JARI</b>			
<b>R</b>			
Eng. To J.S. ....	R120K		6949
Traction .....	P120	2310	6831
<b>JOHN DEERE</b>			
<b>314F</b>			
Drive .....	M128825		6832
<b>518R</b>			
Forward .....	M128980		6827
Reverse .....	M128979		6728
<b>820R</b>			
Forward .....	AM124075		Ⓢ6737
Reverse .....	M128978		6741
<b>JOLLYHOE</b>			
<b>Jollyhoe Giant</b>			
Belt .....			6836
<b>Jollyhoe Giant (Rental)</b>			
Belt .....			6937
<b>Jollyhoe King Size</b>			
Belt .....			6933
<b>Jollyhoe Std.</b>			
Belt; W/32" Belt O.C. ....			6832
Belt; W/33" Belt O.C. ....			6933
<b>KEITH SIMONS</b>			
<b>557; 51021; 51047; 51101</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>KUBOTA</b>			
<b>AT55</b>			
Drive .....	SB37		6938
<b>LAWN BOY</b>			
<b>2020; 2021; LRT-3</b>			
Belt .....	45589		6837
<b>LAWN CHIEF</b>			
<b>5-66</b>			
Forward .....	10737		6831
Reverse .....	10737		6831
<b>H45/4 1/2 H.P. Gardenway</b>			
Drive .....	1128		6473BR
<b>LAZY BOY</b>			
<b>3LBCT</b>			
Drive .....	1228		6828
<b>3MT79; 5MT79; 5MTR79</b>			
Drive .....	9017		6850
<b>5RT</b>			
Eng. To J.S. ....			6849
Tine .....			6868
<b>7-55T; 8-35T Master Till; 8-36T Master Till</b>			
Drive .....	9017		6850
<b>8RT</b>			
Tine .....			6866
Trans. ....			6847
Wheel Drive .....			6834
<b>8T-265 Master Till</b>			
Drive .....	9017		6850
<b>756T</b>			
Drive .....	1244		6850
<b>Economizer</b>			
Belt; W/3 H.P. Eng. ....			6828
<b>LB5RJ</b>			
J.S. To Tine .....	1257		6865

ⓈTwo Required

**TILLERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>LAZY BOY - Continued</b>			
LT3022 Drive .....	1228		6828
LT5084; S26S Drive .....	1244		6850
T-9 Du-O-Tiller; T-9 Master Till Drive .....			6850
T1011 Drive; W/Tecumseh 1.6 H.P. Eng. ....	50036	2310	6831
T3022 Drive; W/B. & S. 3 H.P. Eng. ....	1228	2280	6828
T5034; T5044 Forward .....	1244		6850
T5054 J.S. To Tine .....	1257		6865
T5063 Reverse; W/B. & S. 5 H.P. Eng. .... Tine; W/B. & S. 5 H.P. Eng. .... Wheel Drive; W/B. & S. 5 H.P. Eng. ....	60018 60016 60017	1275	6841 6825
T5074 Forward .....	1244		6850
Reverse .....	1246		6836
T8054 Eng. To Clutch Pulley; W/B. & S. 8 H.P. Eng. .... Pulley To Chain Drive; W/B. & S. 8 H.P. Eng. ....	1255 1257		6847 6865
TV76-3 Du-O-Tiller; TV76-3 Master Till; TV865-80 Du-O-Tiller; TV865-80 Master Till Drive .....			6850
W3-C3T; W3-C5T Drive .....	9017		6850
<b>MANG</b>			
91 Belt; W/45" Belt O.C. .... Belt; W/47" Belt O.C. ....	Q2808 Q2808K		②6945 ②6947
95 Belt; W/45" Belt O.C.; W/Dual Belts ..... Belt; W/45" Belt O.C.; W/Single Belt ..... Belt; W/47" Belt O.C. ....	Q2808 Q2808K		②6945 6945 ②6947
GT Belt .....			6827
JR Belt; Ser. No. 792066 & Before ..... Belt; Ser. No. 792067 & After .....	JR5311 JR5343		6838 6943
JR2000 Belt; W/B. & S. 7 H.P. Eng. ....	5343		B40
<b>MASSEY FERGUSON</b>			
22S; 26S Forward .....	1023435M1		6834
Reverse .....	1023436M1		6829
<b>MASTER TILL</b>			
MT263; MT265 Drive .....	L450		6850
MT265R Forward .....	L450		6850
Reverse .....			6735
<b>MAUSFIERES-SWITZERLAND</b>			
215-385 Drive .....	7540192		6834
<b>MAXIM</b>			
6M50B Tine; W/B. & S. 3, 5 H.P. Eng. ....	359328		6850

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MAXIM - Continued</b>			
Big M Heavy Duty (Garden Plow); Big M Special Tine .....	M35932850		6850
Commercial; Extra Heavy Duty Eng. To Chain Drive .....	272201		6851
GA50B Gardenall; GM50B Garden Master; GM50BP Garden Master Idler .....	320359328		6850
M530B; M550B Tine; W/B. & S. 3, 5 H.P. Eng. ....	359328		6850
MS50B; MS50BR Idler .....	359328		6850
MT50B Red Max Idler .....	320272201		6851
PH50B Traction; W/5 H.P. Eng. ....	272212		6864
RM30B Drive; W/3 H.P. Eng. ....	272241		6837
RT50B J.S.; W/5, 8 H.P. Eng. .... Wheel Drive; W/5, 8 H.P. Eng. ....	272220 272205	2400	6828 6840
RT50B Deluxe Forward .....	320272213		6847
Reverse .....	320272214		6875
TP50B Till-N Plow Idler .....	320272201		6851
TP50B-R Till-N Plow Reverse .....			6746
Trans.; W/50" Belt O.C. ....	359328		6850
Trans.; W/51" Belt O.C. ....	272201		6851
<b>MERRY TILLER</b>			
7402 Belt; W/B. & S. 5 H.P. Eng. .... Belt; W/Tecumseh 4 H.P. Eng. ....	2059 2059		6850 6850
7403 Belt; W/45" Belt O.C. .... Belt; W/50" Belt O.C. ....	2313 2059		6745 6850
7412; 7460; 7480 Belt; W/B. & S. 5 H.P. Eng. .... Belt; W/Tecumseh 4 H.P. Eng. ....	2059 2059		6850 6850
7600; 7601; 7602 Belt; W/International B. & S. 5 H.P. Eng. ...	2278		6841
Custom 7300; Custom G78 Belt; W/Tecumseh 4 H.P. Eng. ....	2059		6850
Exporter G-60 Belt .....	2391		6836
Exporter G-61 Belt; W/International B. & S. 5 H.P. Eng. ...	2278		6841
Exporter G-89 Belt .....	2391		6836
Exporter G-91 Belt .....	2270		6841
Minnie 2000 Belt; W/B. & S. 2 H.P. Eng. ....	3292	2340	6834
Minnie 2003 Belt; W/B. & S. 3 H.P. Eng. .... Belt; W/Tecumseh 4 H.P. Eng. ....	2059 2059		6850 6850
Professional 85; Professional 88 Belt; W/45" Belt O.C. .... Belt; W/50" Belt O.C. ....	2313 2059		6745 6850
Professional 7500; Professional 7501; Professional 7502 Belt .....	2059		6850

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MERRY TILLER - Continued</b>			
<b>Professional G-54</b>			
Belt .....	2031		6850
<b>Professional G-55</b>			
Belt .....	1984		6845
<b>Professional G-83</b>			
Belt; W/45" Belt O.C. ....	1984		6845
Belt; W/B. & S. 5 H.P. Eng.; W/50" Belt O.C. ....	2059		6850
Belt; W/Kohler 4 H.P. Eng.; W/50" Belt O.C. ....	2059		6850
Belt; W/Wisconsin 4.6 H.P. Eng.; W/50" Belt O.C. ....	2059		6850
<b>Scotsman 7200; Scotsman G-44-B</b>			
Belt; W/Tecumseh 4 H.P. Eng. ....	2059		6850
<b>Suburban G-15; Suburban G-19; Suburban G-20; Suburban G-25; Suburban G-26; Suburban G-31; Suburban G-32; Suburban G-38; Suburban G-39</b>			
Forward .....	329		6845
Reverse .....	1637		6739
<b>Suburban G-46-B</b>			
Belt .....	2031		6850
<b>Suburban G-53; Suburban G-53B; Suburban G-80</b>			
Belt; W/Tecumseh 4 H.P. Eng. ....	2059		6850
<b>Suburban G-82</b>			
Belt; W/45" Belt O.C. ....	2313		6745
Belt; W/50" Belt O.C. ....	2059		6850
<b>MIGHTY MAC</b>			
<b>324; 524</b>			
Forward .....			6850
<b>524R</b>			
Forward .....			6850
Reverse .....			6745
<b>822TR</b>			
Forward .....	7010319		6854
Reverse .....	7010318		6842
<b>824; 824RT</b>			
Forward .....			②3V600
Reverse; W/40" Belt O.C. ....			6840
Reverse; W/50" Belt O.C. ....			6850
<b>MITCHELL MFG. CO.</b>			
<b>MTH-3; MTH-3R; MTH-4R; MTH-5R</b>			
Forward .....	T6567		6837
Reverse .....	T6566		6731
<b>MONO</b>			
<b>Mono CD-30</b>			
Drive .....	G1458	2420	6842
<b>Mono CD-50</b>			
Drive .....	G1458	2420	6842
Reverse .....		2318	
<b>Mono T35-BR</b>			
Drive .....	G158		6831
<b>Mono T50-BR</b>			
Drive .....	G158		6831
Reverse .....	G608		6826
<b>Mono TH50-BR</b>			
Drive .....	G820		6832
Reverse .....	G1330		6835
<b>Rocket 30CD</b>			
Drive .....	G1458		6842
Reverse .....	G1461	2318	
<b>Rocket 35-TR</b>			
Drive .....	G158		6831

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONO - Continued</b>			
<b>Rocket 50CD</b>			
Drive .....	G1458		6842
Reverse .....	G1461	2318	
<b>Rocket 50TH</b>			
Drive .....	G820		6832
Reverse .....	G1330		6835
<b>Rocket 50-TR</b>			
Drive .....	G158		6831
<b>MONTGOMERY WARD</b>			
<b>89-1555</b>			
Forward .....	40041		6840
Reverse .....	40207		6845
<b>1545</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>1548</b>			
Reverse .....	1508		6858
<b>1555</b>			
Belt .....	27093		6847
<b>1558</b>			
Reverse .....	1508		6858
<b>1565; 1565E; 1565F; 1565G</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>1566C</b>			
Drive .....	1526		6822
<b>1567</b>			
Forward .....	1110		6835
<b>1578B</b>			
Drive .....	1526		6822
<b>1579A</b>			
Forward .....	4052		6855
Reverse .....	4051		6731
<b>1580</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>1582A; 1582B</b>			
Forward .....	7740		6838
Reverse .....	7838		6734
<b>1589</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>1590</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>1593</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>1595</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>1596; 1596A</b>			
Forward .....	7740		6838
Reverse .....	7838		6734
<b>5030-0</b>			
Forward .....	40041		6840
Reverse .....	40207		6845
<b>39002B</b>			
Drive .....	36019		6720
<b>39007A; GIL1494B; GIL1545A; GIL1545B; GIL1545C; GIL1545D</b>			
Forward .....	1110		6835
Reverse .....	6163		6737

②Two Required

TILLERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>GIL1555A</b>			
Belt .....	27093		6847
Forward .....	1110		6835
Reverse .....	6163		6737
<b>GIL1555B; GIL1555C</b>	27093		6847
Belt .....			
<b>GIL1565E; GIL1565F; GIL1565G</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>GIL1566C</b>			
Forward .....	1526		6822
<b>GIL1567A; GIL1567AB</b>			
Forward .....	1110		6835
<b>GIL1575</b>			
Lower Drive .....	26345		6830
Upper Drive .....	26344		6819
<b>GIL1578A; GIL1578B</b>			
Forward .....	1526		6822
<b>GIL1579A</b>			
Forward .....	4052		6855
Reverse .....	4051		6731
<b>GIL1580A; GIL1580B; GIL1580C; GIL1580D; GIL1580E; GIL1580F; GIL1580G; GIL1580H; GIL1580I; GIL1580J</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>GIL1580K</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>GIL1581; GIL1581A</b>			
Forward .....	1526		6822
<b>GIL1582A; GIL1582B</b>			
Forward .....	7740		6838
Reverse .....	7838		6734
<b>GIL1584A; GIL1584B; GIL1584C</b>			
Forward .....	1526		6822
<b>GIL1585</b>			
Lower Drive .....	26345		6830
Upper Drive .....	26344		6819
<b>GIL1589A</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>GIL1590A</b>			
Belt .....			6739
<b>GIL1593A; GIL1593B; GIL1593C; GIL1593D; GIL1594A; GIL1594B</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>GIL1595E</b>			
Belt .....			6739
<b>GIL1596; GIL1596A</b>			
Forward .....	7740		6838
Reverse .....	7838		6734
<b>GIL1598B; GIL1599B</b>			
Belt .....	1040		6832
<b>GIL33095A; GIL33095B</b>		3560	
Belt .....	12570		
<b>GIL33498A</b>			
Belt .....	214170		6858
<b>GIL39000A; GIL39000B</b>			
Drive .....	33622		6727
<b>GIL39008A</b>			
Traction .....	208526		6738

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>GIL39011D</b>			
Forward .....	208301		6833
Reverse .....	208626		6727
<b>GIL39012B</b>			
Tine .....	200554		6846
Traction .....	200555		6746
<b>GIL51174</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>TMO39084A</b>			
Forward .....	7540109		6843
Reverse .....	7540190		6839
Tine .....	7540195		6854
<b>TMO39000</b>			
Drive .....	33622		6727
<b>TMO39014B; TMO39014C</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>TMO39023; TMO39023A; TMO39023B; TMO39023C</b>			
Tine .....	7540190		6839
<b>TMO39025; TMO39025A</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>TMO39031</b>			
Drive .....	208301		6833
<b>TMO39032A</b>			
Traction .....	200555		6746
<b>TMO39080A</b>			
Drive; W/37" Belt O.C. ....	7540255		6837
Drive; W/44" Belt O.C. ....	7540189		6844
<b>TMO39083A</b>			
Forward .....	7540109		6843
Reverse .....	7540190		6839
Tine .....	7540195		6854
<b>TMO39085A; TMO39085B; TMO39086A</b>			
Tine .....	7540325		6857
<b>TMO39097; TMO39097A</b>			
Belt; W/43" Belt O.C. ....	7540109		6843
Belt; W/54" Belt O.C. ....	7540195		6854
<b>TMO39103; TMO39103A; TMO39103B; TMO39103C</b>			
Eng. To Variator .....	7540220		6927
Variator To Trans. ....	7540268		6951
<b>TMO219310</b>			
Belt; W/39" Belt O.C. ....	7540190		6839
Belt; W/44" Belt O.C. ....	7540189		6844
<b>TMO218355088</b>			
Drive; W/37" Belt O.C. ....	7540255		6837
Drive; W/44" Belt O.C. ....	7540189		6844
<b>MOTO-MOWER</b>			
<b>26-500; 61-501; 61-502; 1900-10; Deluxe 500; Deluxe 501; Deluxe 502</b>			
Belt; W/29" Belt O.C. ....	1016174		6829
Belt; W/34" Belt O.C. ....	1016169		6834
<b>MTD GOLD</b>			
<b>21AB45M5004</b>			
Drive .....	9540434		6858
<b>MTD PRODUCTS, INC.</b>			
<b>9-5204</b>			
Drive .....	7540216		6729
<b>9-5208</b>			
Drive .....	7540190		6839



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>21-4620; 21-4621</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>21A035</b>			
Drive .....	9540216		6729
<b>21A213</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>21A214; 21A215</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>21A217</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>21A340</b>			
Drive .....	9540428		6842
<b>21A390</b>			
Forward .....	9540428		6842
Reverse .....	9540429		6746
<b>21A410; 21A410A; 21A420; 21A422B</b>			
Drive .....	9540438		6851
<b>21A430; 21A447; 21A448; 21A452B; 21A456B; 21A457A; 21A457B; 21A458B</b>			
Drive .....	9540434		6858
<b>100-129</b>			
Belt .....	7540103		6827
<b>200-027</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>210-030A</b>			
Drive .....	7540216		6729
<b>210-100</b>			
Belt .....	7540103		6827
<b>210-100A</b>			
Belt .....	7540196		6830
<b>210-200; 210-250</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>210-300A; 210-320A</b>			
Drive .....	7540190		6839
<b>210-350; 210-352</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>210-355A</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>210-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>210-385A</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>210-386A</b>			
Eng. To Variator .....	7540232		6820
Variator To Drive .....	7540231		6828
<b>210-388; 210-388A</b>			
Belt; W/21" Belt O.C. ....	7540233		6821
Belt; W/28" Belt O.C. ....	7540231		6828
<b>210-405; 210-405A</b>			
Eng. To Variator .....	7540224		6926
Variator To Drive .....	7540221		6952
<b>210-408; 210-408A; 210-409; 210-409A</b>			
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/52" Belt O.C. ....	7540221		6952

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>211-030A</b>			
Drive .....	7540216		6729
<b>211-100</b>			
Belt .....	7540103		6827
<b>211-200; 211-255</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>211-300A; 211-320A</b>			
Drive .....	7540190		6839
<b>211-355</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>211-355A</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>211-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>211-365; 211-370</b>			
Belt; W/35" Belt O.C. ....	7540158		6935
Belt; W/37" Belt O.C. ....	7540154		6837
Belt; W/40" Belt O.C. ....	7540155		6509BR
<b>211-375; 211-380</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>211-381; 211-385A</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>211-386A; 211-388; 211-388A</b>			
Eng. To Variator .....	7540232		6820
Variator To Drive .....	7540231		6828
<b>211-405A; 211-408A</b>			
Eng. To Variator .....	7540224		6926
Variator To Drive .....	7540221		6952
<b>212-030</b>			
Drive .....	7540216		6729
<b>212-100</b>			
Belt .....	7540103		6827
<b>212-200; 212-255</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>212-300</b>			
Drive .....	7540190		6839
<b>212-355</b>			
Forward; W/31" Belt O.C. ....	7540121		6831
Forward; W/37" Belt O.C. ....	7540154		6837
Reverse; W/33" Belt O.C. ....	7540146		6833
Reverse; W/44" Belt O.C. ....	7540189		6844
<b>212-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>212-365; 212-370</b>			
Belt; W/35" Belt O.C. ....	7540158		6935
Belt; W/37" Belt O.C. ....	7540154		6837
Belt; W/40" Belt O.C. ....	7540155		6509BR
<b>212-375</b>			
Belt; W/39" Belt O.C. ....	7540190		6839
Belt; W/44" Belt O.C. ....	7540189		6844
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>212-380</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>212-381</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841

Lawn & Garden Equipment



**TILLERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>212-386</b>			
Forward .....	7540254		6819
Reverse .....	7540265		6829
<b>212-405</b>			
Eng. To Variator .....	7540224		6926
Variator To Drive .....	7540221		6952
<b>212-410; 212-412</b>			
Belt; W/26" Belt O.C. ....	7540224		6926
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/51" Belt O.C. ....	7540268		6951
<b>213-030</b>			
Drive .....	7540216		6729
<b>213-100</b>			
Belt .....	7540103		6827
<b>213-200; 213-225; 213-255</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>213-300; 213-320</b>			
Drive .....	7540190		6839
<b>213-350</b>			
Belt; W/32" Belt O.C. ....	7540177	2320	6832
Belt; W/33" Belt O.C. ....	7540146		6833
Belt; W/62" Belt O.C. ....	7540166		6962
<b>213-355</b>			
Belt; W/32" Belt O.C. ....	7540177	2320	6832
Belt; W/33" Belt O.C. ....	7540146		6833
Belt; W/62" Belt O.C. ....	7540166		6962
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>213-360</b>			
Belt; W/32" Belt O.C. ....	7540177	2320	6832
Belt; W/33" Belt O.C. ....	7540146		6833
Belt; W/62" Belt O.C. ....	7540166		6962
<b>213-370; 213-375</b>			
Belt; W/35" Belt O.C. ....	7540158		6935
Belt; W/37" Belt O.C. ....	7540154		6837
Belt; W/40" Belt O.C. ....	7540155		6509BR
<b>213-380</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>213-381</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>213-385; 213-390A; 213-395A</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>213-404</b>			
Tine .....	7540253		6843
Traction .....	7540195		6854
<b>213-410; 213-412</b>			
Belt; W/26" Belt O.C. ....	7540224		6926
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/51" Belt O.C. ....	7540268		6951
<b>214-021; 214-030; 214-031; 214-035</b>			
Drive .....	7540216		6729
<b>214-100; 214-100A; 214-102; 214-104</b>			
Belt .....	7540103		6827
<b>214-200; 214-200A; 214-250; 214-254</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>214-255</b>			
Forward .....	7540107		6830
Reverse; W/25" Belt O.C. ....	7540106		6825
Reverse; W/44" Belt O.C. ....	7540189		6844
<b>214-255A</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>214-257</b>			
Forward .....	7540107		6830
Reverse; W/25" Belt O.C. ....	7540106		6825
Reverse; W/44" Belt O.C. ....	7540189		6844
<b>214-300; 214-304</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>214-310; 214-320</b>			
Drive .....	7540190		6839
<b>214-340</b>			
Drive .....	7540428		6842
<b>214-350</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>214-350A</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>214-354</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>214-355; 214-355A; 214-360A; 214-370; 214-370A</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>214-372</b>			
Belt; W/34" Belt O.C. ....	7540192		6834
Belt; W/37" Belt O.C. ....	7540154		6837
Belt; W/44" Belt O.C. ....	7540189		6844
<b>214-375A</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>214-380A</b>			
Tine .....	7540192		6834
<b>214-381</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>214-382A</b>			
Tine .....	7540192		6834
<b>214-385</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>214-385A</b>			
Tine .....	7540192		6834
<b>214-386</b>			
Tine .....	7540146		6833
<b>214-390</b>			
Forward .....	7540428		6842
Reverse .....	7540429		6746
<b>214-390A; 214-395A</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>214-404; 214-405</b>			
Tine .....	7540109		6843
Traction .....	7540195		6854
<b>214-406</b>			
Forward .....	7540109		6843
Reverse .....	7540190		6839
Tine .....	7540195		6854
<b>214-410</b>			
Drive .....	7540438		6851
<b>214-412; 214-418</b>			
Belt; W/26" Belt O.C. ....	7540224		6926
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/51" Belt O.C. ....	7540268		6951
<b>214-420</b>			
Drive .....	7540438		6851



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>214-430; 214-447</b>			
Drive .....	7540267		6859
<b>215-030; 215-031</b>			
Drive .....	7540216		6729
<b>215-100</b>			
Belt; W/27" Belt O.C. ....	7540103		6827
Belt; W/30" Belt O.C. ....	7540196		6830
<b>215-100A; 215-100AB2</b>			
Belt .....	7540196		6830
<b>215-104</b>			
Belt; W/27" Belt O.C. ....	7540103		6827
Belt; W/30" Belt O.C. ....	7540196		6830
<b>215-200; 215-200A; 215-200AB2</b>			
Forward .....	7540196		6830
Reverse .....	7540106		6825
<b>215-204; 215-250; 215-254; 215-255</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>215-255A; 215-255AB2</b>			
Forward .....	7540196		6830
Reverse .....	7540106		6825
<b>215-300; 215-304</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>215-310; 215-320</b>			
Drive .....	7540190		6839
<b>215-350; 215-354</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>215-355; 215-355A; 215-355AB2; 215-360; 215-360A; 215-360AB2; 215-370; 215-370A; 215-370AB2</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>215-375; 215-375A</b>			
Belt; W/39" Belt O.C. ....	7540190		6839
Belt; W/44" Belt O.C. ....	7540189		6844
<b>215-381</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>215-382; 215-382A; 215-385; 215-385A</b>			
Tine .....	7540192		6834
<b>215-386</b>			
Forward .....	7540254		6819
Reverse .....	7540265		6829
<b>215-390; 215-390A; 215-395; 215-395A</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>215-402</b>			
Tine .....	7540109		6843
Traction .....	7540195		6854
<b>215-403</b>			
Belt; W/42" Belt O.C. ....	7540207		6842
Belt; W/54" Belt O.C. ....	7540195		6854
<b>215-404; 215-405</b>			
Tine .....	7540109		6843
Traction .....	7540195		6854
<b>215-406</b>			
Forward .....	7540109		6843
Reverse .....	7540190		6839
Tine .....	7540195		6854
<b>215-412; 215-418</b>			
Belt; W/26" Belt O.C. ....	7540224		6926
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/51" Belt O.C. ....	7540268		6951

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>216-030; 216-031</b>			
Drive .....	7540216		6729
<b>216-100</b>			
Belt .....	7540103		6827
<b>216-100A</b>			
Belt .....	7540196		6830
<b>216-104</b>			
Belt .....	7540103		6827
<b>216-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>216-200A</b>			
Forward .....	7540196		6830
Reverse .....	7540106		6825
<b>216-204; 216-250; 216-254</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>216-300; 216-304</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>216-310; 216-320</b>			
Drive .....	7540190		6839
<b>216-350; 216-354</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>216-355A</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>216-360</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>216-360A; 216-370A</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>216-375; 216-375A</b>			
Belt; W/39" Belt O.C. ....	7540190		6839
Belt; W/44" Belt O.C. ....	7540189		6844
<b>216-380; 216-380A; 216-381; 216-382; 216-382A; 216-385; 216-385A</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>216-386</b>			
Belt; W/29" Belt O.C. ....	7540265		6829
Belt; W/59" Belt O.C. ....	7540245		6859
<b>216-390A; 216-395A</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>216-402</b>			
Belt; W/43" Belt O.C. ....	7540109		6843
Belt; W/54" Belt O.C. ....	7540195		6854
<b>216-403; 216-404; 216-405; 216-406</b>			
Forward .....	7540109		6843
Reverse .....	7540190		6839
Tine .....	7540195		6854
<b>216-412; 216-418</b>			
Belt; W/26" Belt O.C. ....	7540224		6926
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/51" Belt O.C. ....	7540268		6951
<b>216-420; 216-430</b>			
Belt .....	7540325		6857
<b>217-020</b>			
Belt; W/29" Belt O.C. ....	7540216		6729
Belt; W/79" Belt O.C. ....	7540217		6979
<b>217-020A; 217-030A</b>			
Belt .....	7540196		6830

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
217-031 Drive .....	7540216		6729
217-100 Belt; W/27" Belt O.C. ....	7540103		6827
Belt; W/30" Belt O.C. ....	7540196		6830
217-100A Belt .....	7540196		6830
217-200 Forward .....	7540107		6830
Reverse .....	7540106		6825
217-200A Forward .....	7540196		6830
Reverse .....	7540106		6825
217-250 Forward .....	7540107		6830
Reverse .....	7540106		6825
217-300 Forward .....	7540104		6832
Reverse .....	7540103		6827
217-310; 217-320 Drive .....	7540190		6839
217-350 Forward; W/32" Belt O.C. ....	7540104		6832
Forward; W/37" Belt O.C. ....	7540154		6837
Reverse; W/27" Belt O.C. ....	7540103		6827
Reverse; W/44" Belt O.C. ....	7540189		6844
217-355A Forward .....	7540154		6837
Reverse .....	7540189		6844
217-360 Forward .....	7540104		6832
Reverse .....	7540103		6827
217-370A Forward .....	7540154		6837
Reverse .....	7540189		6844
217-375 Forward .....	7540154		6837
Reverse .....	7540190		6839
217-375A Belt; W/39" Belt O.C. ....	7540190		6839
Belt; W/44" Belt O.C. ....	7540189		6844
217-380A; 217-381; 217-385A Forward .....	7540154		6837
Reverse .....	7540201		6841
217-390A; 217-395; 217-395A Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
217-402 Belt; W/42" Belt O.C. ....	7540207		6842
Belt; W/54" Belt O.C. ....	7540195		6854
217-403 Forward .....	7540109		6843
Reverse .....	7540190		6839
Tine .....	7540195		6854
217-404; 217-405 Tine .....	7540109		6843
Traction .....	7540195		6854
217-406 Forward .....	7540109		6843
Reverse .....	7540190		6839
Tine .....	7540195		6854
217-408; 217-408A Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/52" Belt O.C. ....	7540221		6952
217-412 Belt; W/26" Belt O.C. ....	7540224		6926

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
217-412 - Continued Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/51" Belt O.C. ....	7540268		6951
217-420; 217-430 Belt .....	7540325		6857
218-020A Belt .....	7540196		6830
218-030 Drive .....	7540216		6729
218-030A Belt .....	7540196		6830
218-031 Drive .....	7540216		6729
218-100 Belt .....	7540103		6827
218-100A Belt .....	7540196		6830
218-200; 218-250; 218-255 Forward .....	7540107		6830
Reverse .....	7540106		6825
218-300 Forward .....	7540104		6832
Reverse .....	7540103		6827
218-310 Drive .....	7540190		6839
218-350 Forward .....	7540104		6832
Reverse .....	7540103		6827
218-355; 218-355A Forward .....	7540154		6837
Reverse .....	7540189		6844
218-360; 218-361 Forward .....	7540104		6832
Reverse .....	7540103		6827
218-370A Forward .....	7540154		6837
Reverse .....	7540189		6844
218-375A Belt; W/39" Belt O.C. ....	7540190		6839
Belt; W/44" Belt O.C. ....	7540189		6844
218-380A Forward .....	7540154		6837
Reverse .....	7540189		6844
218-381 Drive; W/37" Belt O.C. ....	7540154		6837
Drive; W/42" Belt O.C. ....	7540207		6842
218-385; 218-385A Forward .....	7540154		6837
Reverse .....	7540201		6841
218-386A; 218-388A Eng. To Variator .....	7540232		6820
Variator To Drive .....	7540231		6828
218-402 Belt; W/42" Belt O.C. ....	7540207		6842
Belt; W/54" Belt O.C. ....	7540195		6854
218-403 Drive; W/39" Belt O.C. ....	7540190		6839
Drive; W/43" Belt O.C. ....	7540109		6843
218-0404; 218-405 Tine .....	7540109		6843
Traction .....	7540195		6854
218-405A Eng. To Variator .....	7540224		6926
Variator To Drive .....	7540221		6952



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>218-406</b>			
Drive; W/39" Belt O.C. ....	7540190		6839
Drive; W/43" Belt O.C. ....	7540109		6843
Reverse ..... 7540131			6671BR
<b>218-408; 218-408A</b>			
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/52" Belt O.C. ....	7540221		6952
<b>218-430</b>			
Belt ..... 7540325			6857
<b>219-030A</b>			
Drive ..... 7540216			6729
<b>219-100; 219-100A</b>			
Belt ..... 7540196			6830
<b>219-200; 219-250</b>			
Forward ..... 7540107			6830
Reverse ..... 7540106			6825
<b>219-310; 219-320</b>			
Drive ..... 7540190			6839
<b>219-350</b>			
Forward ..... 7540103			6827
Reverse ..... 7540121			6831
<b>219-355; 219-355A</b>			
Forward ..... 7540154			6837
Reverse ..... 7540189			6844
<b>219-360</b>			
Forward ..... 7540121			6831
Reverse ..... 7540103			6827
<b>219-380; 219-380A; 219-381; 219-385;</b>			
<b>219-385A</b>			
Forward ..... 7540154			6837
Reverse ..... 7540201			6841
<b>219-386A</b>			
Belt; W/20" Belt O.C. ....	7540232		6820
Belt; W/21" Belt O.C. ....	7540233		6821
<b>219-388A</b>			
Belt; W/21" Belt O.C. ....	7540233		6821
Belt; W/28" Belt O.C. ....	7540231		6828
<b>219-405</b>			
Eng. To Variator ..... 7540224			6926
Tine ..... 7540109			6843
Traction ..... 7540195			6854
Variator To Drive ..... 7540221			6952
<b>219-405A</b>			
Eng. To Variator ..... 7540224			6926
Variator To Drive ..... 7540221			6952
<b>219-406</b>			
Tine ..... 7540109			6843
Traction ..... 7540195			6854
<b>219-408; 219-408A</b>			
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/52" Belt O.C. ....	7540221		6952
<b>219-430</b>			
Belt; W/57" Belt O.C. ....	7540325		6857
<b>223-0831</b>			
Forward ..... 7540154			6837
Reverse ..... 7540201			6841
<b>223-3160</b>			
Belt; W/39" Belt O.C. ....	7540190		6839
Belt; W/44" Belt O.C. ....	7540189		6844
<b>223-3271</b>			
Drive ..... 7540114		2240	6824
Gen. .... 7540169		7355	
P.T.O. .... 7540165			6834
Trans. .... 7540124			6857
<b>223-3276</b>			
Belt ..... 7540103			6827

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>223-3277</b>			
Forward ..... 7540104			6832
Reverse ..... 7540103			6827
<b>223-3412</b>			
Belt ..... 7540196			6830
<b>223-3422</b>			
Drive ..... 7540216			6729
<b>223-3423</b>			
Belt ..... 7540196			6830
<b>223-3424</b>			
Forward ..... 7540154			6837
Reverse ..... 7540189			6844
<b>223-7930; 223-7931</b>			
Forward ..... 7540154			6837
Reverse ..... 7540201			6841
<b>223-8430</b>			
Drive ..... 7540216			6729
<b>223-8431</b>			
Tine ..... 7540192			6834
<b>223-8432</b>			
Tine ..... 7540109			6843
Traction ..... 7540195			6854
<b>250-129</b>			
Forward ..... 7540107			6830
Reverse ..... 7540106			6825
<b>310-100A</b>			
Drive ..... 7540223			6736
<b>310-230A; 310-430A</b>			
Drive ..... 7540205			6673BR
<b>310-860A; 310-960A</b>			
Blower ..... 7540194			6845
Traction ..... 7540131			6671BR
<b>643-0905</b>			
Belt ..... 7540103			6827
<b>643-0906; 643-0908; 643-0909</b>			
Forward ..... 7540107			6830
Reverse ..... 7540106			6825
<b>643-910</b>			
Forward ..... 7540121			6831
Reverse ..... 7540104			6832
<b>643-2194</b>			
Forward ..... 7540166			6962
Reverse ..... 7540146			6833
<b>643-2196</b>			
Forward ..... 7540196			6830
Reverse ..... 7540106			6825
<b>643-2197</b>			
Forward ..... 7540154			6837
Reverse ..... 7540189			6844
<b>2002A88</b>			
Drive ..... 7540190			6839
<b>2010A57</b>			
Belt ..... 7540154			6837
<b>5033-41</b>			
Drive ..... 7540216			6729
<b>5053-41</b>			
Tine ..... 7540109			6843
Traction ..... 7540195			6854
<b>5054-41</b>			
Drive ..... 7540190			6839
<b>5083-41</b>			
Belt; W/26" Belt O.C. ....	7540224		6926
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/51" Belt O.C. ....	7540268		6951

Lawn & Garden Equipment

**TILLERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>6423</b>			
Belt .....	7540196		6830
<b>6424</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>6426</b>			
Forward .....	7540190		6839
Reverse .....	7540189		6844
<b>6477</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>50071</b>			
Belt .....	7540196		6830
<b>50401</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>50411</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>50421</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>50497</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>50498; 50499</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>50633</b>			
Drive .....	7540216		6729
<b>50634</b>			
Drive .....	7540190		6839
<b>50635</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>50636</b>			
Tine .....	7540109		6843
Traction .....	7540195		6854
<b>50771; 50772</b>			
Drive .....	7540216		6729
<b>50773</b>			
Drive .....	7540190		6839
<b>50777; 50781; 50888</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>T1006</b>			
Belt .....	7540196		6830
<b>T3350; T3355; T3556; T3558; T3559</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>Z2005</b>			
Forward .....	7540196		6830
Reverse .....	7540106		6825
<b>Z3554; Z3555; Z3556</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>Z3586</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>MURRAY</b>			
<b>0-1000</b>			
Trans. ....	75370		6726
<b>1-13020; 4-13051</b>			
Forward .....	37X28		6848

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>1-13020; 4-13051 - Continued</b>			
Reverse .....	37X29		6739
<b>4-13450</b>			
Belt .....	37X32		6845
<b>5-10030</b>			
Tine .....	37X28		6848
<b>5-13051</b>			
Forward .....	37X28		6848
Reverse .....	37X29		6739
<b>6-1200</b>			
Belt .....	75121		6848
<b>6-13051</b>			
Forward .....	37X28		6848
Reverse .....	37X29		6739
<b>7-1000</b>			
Trans. ....	75370		6726
<b>7-1190</b>			
Belt .....	75121		6848
<b>7-1202; 7-1203</b>			
Forward .....	75121		6848
Reverse .....	75147		6739
<b>7-10030</b>			
Drive .....	37X46		6827
<b>7-13051</b>			
Forward .....	37X28		6848
Reverse .....	37X29		6739
<b>8-1000</b>			
Trans. ....	75370		6726
<b>8-1190</b>			
Belt .....	75121		6848
<b>8-1202; 8-1203</b>			
Forward .....	75121		6848
Reverse .....	75147		6739
<b>9-1000</b>			
Trans. ....	75370		6726
<b>9-1190</b>			
Belt .....	75121		6848
<b>9-1202; 9-1203</b>			
Forward .....	75121		6848
Reverse .....	75147		6739
<b>61-0030</b>			
Tine .....	37X46		6827
<b>61-13450</b>			
Belt .....	37X32		6845
<b>63-3051</b>			
Forward .....	37X28		6848
<b>81-13020; 82-13051; 83-13051</b>			
Forward .....	37X28		6848
Reverse .....	37X29		6739
<b>84-13450</b>			
Belt .....	37X32		6845
<b>11500A</b>			
Drive .....	1245	3240	
<b>12000A</b>			
Forward .....	1254		6849
Reverse .....	1257		6865
Wheel Drive .....			6833
<b>NEW HOLLAND</b>			
<b>RT-3; RT-5</b>			
Forward .....	1110		6835
Reverse .....	6163		6737





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA</b>			
<b>2805-0000; 2805-1200</b>			
Drive; W/38" Belt O.C. ....	50876		6738
Drive; W/41" Belt O.C. ....	50877		6741
<b>5300-0</b>			
Drive .....	8271		6827
<b>5333-0000; 5333-0600; 5333-0700; 5333-0800;</b>			
<b>5333-0900; 5333-1000; 5333-1100; 5333-1200;</b>			
<b>5333-1300</b>			
Drive .....	50876		6738
<b>5334-0000; 5334-0600; 5335-0000; 5335-0100;</b>			
<b>5335-0200; 5336-0400; 5336-0500</b>			
Drive .....	45216		6843
<b>5336-0600</b>			
Drive .....	45217		6839
<b>5336-0800</b>			
Drive .....	45216		6843
<b>5336-0900; 5336-1500</b>			
Drive .....	45217		6839
<b>5343-0000; 5343-0001; 5343-0100; 5343-3000;</b>			
<b>5343-3700; 5343-3900; 5343-04000;</b>			
<b>5344-0000; 5344-3500</b>			
Drive .....	21865		6826
<b>5345-0000; 5345-0001; 5345-0200; 5345-0300;</b>			
<b>5345-3000; 5345-3200; 5345-3300; 5345-3500;</b>			
<b>5345-3600; 5345-3800</b>			
Belt .....	21865		6826
<b>5345-4300; 5345-4500; 5345-4700; 5345-4900;</b>			
<b>5345-5000; 5345-5100; 5345-5300</b>			
Belt .....	21865		6826
<b>5346-0000; 5346-0100; 5346-0200; 5346-0300;</b>			
<b>5346-0400; 5346-0500; 5346-0600; 5346-0700;</b>			
<b>5346-0800; 5346-1000</b>			
Drive .....	21865		6826
<b>5346-1100; 5346-1200; 5346-1400; 5346-3000;</b>			
<b>5346-4200; 5346-4400; 5346-4600</b>			
Drive .....	21865		6826
<b>5347-0000</b>			
Drive .....	28148		6826
<b>5347-0100</b>			
Drive .....	21865		6826
<b>5347-0200</b>			
Drive .....	28148		6826
<b>5347-0400</b>			
Drive .....	21865		6826
<b>5347-3000; 5347-3100; 5347-3300; 5347-3400;</b>			
<b>5347-3700</b>			
Drive .....	28148		6826
<b>5347-4000</b>			
Drive .....	21865		6826
<b>5347-4200; 5347-4400; 5347-4500; 5347-4600;</b>			
<b>5347-4700; 5347-4800; 5347-4900; 5347-5200;</b>			
<b>5347-5300; 5347-5400</b>			
Drive .....	28148		6826
<b>5347-5500; 5347-5600; 5347-5700; 5347-5800;</b>			
<b>5347-5801</b>			
Drive .....	28148		6826
<b>5348-0000; 5348-0100; 5348-0200; 5348-0500;</b>			
<b>5348-0600; 5349-0000; 5349-0100; 5349-0200;</b>			
<b>5349-0300; 5349-0400</b>			
Drive; W/38" Belt O.C. ....	32131		6838
Drive; W/39" Belt O.C. ....	32132		6839
<b>5349-0500; 5349-0600; 5349-0700; 5349-0800;</b>			
<b>5349-3300; 5349-4000; 5349-4100; 5349-4200</b>			
Drive; W/38" Belt O.C. ....	32131		6838

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>NOMA - Continued</b>			
<b>5349-0500; 5349-0600; 5349-0700; 5349-0800;</b>			
<b>5349-3300; 5349-4000; 5349-4100; 5349-4200</b>			
<b>- Continued</b>			
Drive; W/39" Belt O.C. ....	32132		6839
<b>5677-0100</b>			
Drive .....	45216		6843
<b>50401-3; 50404; 50406; 50407-3; 50409-4;</b>			
<b>50409-5; 50414; 50416</b>			
Drive .....	28165		6826
<b>50417-1; 50417-3</b>			
Drive .....	28148		6826
<b>50417-4</b>			
Drive .....	28165		6826
<b>50417-5</b>			
Drive .....	28148		6826
<b>50417-6</b>			
Drive .....	28165		6826
<b>50429-4; 50429-6</b>			
Drive; W/38" Belt O.C. ....	32131		6838
Drive; W/39" Belt O.C. ....	32132		6839
<b>A2805-010; B2805-010; C2805-010</b>			
Drive; W/38" Belt O.C. ....	50876		6738
Drive; W/41" Belt O.C. ....	50877		6741
<b>OKLAHOMA TIRE &amp; SUPPLY</b>			
<b>10-267-20</b>			
Forward .....	4052		6855
Reverse .....	4051		6731
<b>11-283-20</b>			
Forward .....	9304		6829
<b>47-303</b>			
Belt .....	7540190		6839
<b>47-307</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>47-310</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>210-200; 210-250; 211-200; 211-255; 212-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>212-335; 212-350; 212-355</b>			
Forward .....	7540177		6832
Reverse .....	7540146		6833
<b>212-375</b>			
Reverse .....	7540158		6935
<b>213-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>213-355</b>			
Forward .....	7540177		6832
Reverse .....	7540146		6833
<b>213-375</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>213-380</b>			
Reverse .....	7540158		6935
<b>214-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>214-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>214-375</b>			
Forward .....	7540190		6839

Lawn & Garden Equipment

**TILLERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>OKLAHOMA TIRE &amp; SUPPLY - Continued</b>			
<b>214-375 – Continued</b>			
Reverse .....	7540189		6844
<b>214-385</b>			
Belt .....	7540192		6834
<b>215-355A; 215-360A</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>215-382A; 215-385A</b>			
Belt .....	7540192		6834
<b>216-355A; 216-360A</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>216-380A; 216-382A; 216-385A</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>216-405</b>			
Tine .....	7540195		6854
Variator .....	7540109		6843
<b>216-416</b>			
Tine .....	7540268		6951
<b>217-355A; 217-360A</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>217-380; 217-380A; 217-385; 217-385A</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>218-200; 218-350; 218-360</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>218-405</b>			
Belt; W/26" Belt O.C. ....	7540224		6926
Belt; W/52" Belt O.C. ....	7540221		6952
<b>218-408</b>			
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/52" Belt O.C. ....	7540221		6952
<b>219-200</b>			
Forward .....	7540103		6827
Reverse .....	7540121		6831
<b>219-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>219-360</b>			
Forward .....	7540103		6827
Reverse .....	7540121		6831
<b>219-385</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>267; 51024</b>			
Forward .....	4052		6855
Reverse .....	4051		6731
<b>OLYMPIA</b>			
<b>MTH-3; MTH-4; MTH-5</b>			
Belt .....	2350		6835
<b>TR-3R; TR-4R; TR-5R</b>			
Belt; W/32" Belt O.C. ....	1310		6732
Belt; W/37" Belt O.C. ....	2370		6837
<b>OUR OWN HARDWARE</b>			
<b>210-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>210-320</b>			
Belt .....	7540190		6839
<b>210-350; 210-360</b>			
Forward .....	7540121		6831

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>OUR OWN HARDWARE - Continued</b>			
<b>210-350; 210-360 – Continued</b>			
Reverse .....	7540146		6833
<b>210-385</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>210-408</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>211-200; 211-255</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>211-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>212-200; 212-255</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>212-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>212-375</b>			
Belt; W/28" Belt O.C. ....	7540157		6928
Belt; W/35" Belt O.C. ....	7540158		6935
<b>213-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>213-355</b>			
Forward .....	7540177		6832
Reverse .....	7540146		6833
<b>213-375</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>214-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>214-310</b>			
Belt .....	7540190		6839
<b>214-360</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>214-382</b>			
Belt .....	7540192		6834
<b>214-404</b>			
Forward .....	7540109		6843
Reverse .....	7540195		6854
<b>215-200</b>			
Forward .....	7540196		6830
Reverse .....	7540106		6825
<b>215-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>215-385</b>			
Belt .....	7540192		6834
<b>216-100</b>			
Belt .....	7540196		6830
<b>216-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>216-385</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>217-031</b>			
Drive .....	7540216		6729
<b>217-310</b>			
Belt .....	7540190		6839



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>OUR OWN HARDWARE - Continued</b>			
<b>217-381; 218-385</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>218-405</b>			
Belt; W/26" Belt O.C. ....	7540224		6926
Belt; W/52" Belt O.C. ....	7540221		6952
<b>PENNEYS</b>			
<b>1806; 1806A</b>			
Belt .....	7540103		6827
<b>1816</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>1820</b>			
Belt; W/32" Belt O.C. ....	7540104		6832
Belt; W/33" Belt O.C. ....	7540146		6833
<b>1826; 1826A; 1836; 1837; 1837A</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>1840; 1840A</b>			
Belt; W/32" Belt O.C. ....	7540104		6832
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>1840B</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>1850</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>1860A</b>			
Belt .....	7540103		6827
<b>3000</b>			
Forward .....	7540177		6832
Reverse .....	7540146		6833
<b>3001-01A; 3001-32; 3001-32A; 3001-32B</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>3008; 3008A; 3009; 3010; 3012</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>3013; 3013B</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>3020</b>			
Forward .....	70073		6834
Reverse .....	248940		6733
<b>3029; 3029A; 3029B</b>			
Forward .....	10738		6836
<b>3030</b>			
Forward .....	70073		6834
Reverse .....	248940		6733
<b>3031</b>			
Forward .....	70073		6834
Reverse .....	70074		6733
<b>3034</b>			
Forward .....	7540220		6927
Reverse .....	7540268		6951
<b>3035</b>			
Forward .....	7540109		6843
Reverse .....	7540195		6854
<b>3040</b>			
Forward .....	10738		6836
Reverse .....	10739		6370
<b>3041; 3041A</b>			
Drive; W/26" Belt O.C. ....	7540224		6926
Drive; W/52" Belt O.C. ....	7540221		6952

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PENNEYS - Continued</b>			
<b>3042</b>			
Forward .....	10737		6831
Reverse .....	10737		6831
<b>3043</b>			
Forward .....	10738		6836
<b>3045</b>			
Forward .....	10737		6831
Reverse .....	10737		6831
<b>3046; 3046A</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>3047</b>			
Drive .....	7540154		6837
<b>3048</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>3050</b>			
Forward .....	7540196		6830
Reverse .....	7540106		6825
<b>PIONEER</b>			
<b>5 H.P.</b>			
Forward .....		2370	
Reverse .....		1310	
<b>POWER EQUIPMENT</b>			
<b>Tiller</b>			
Belt .....	9017		6850
<b>PRECISION VALLEY MFG. CO.</b>			
<b>Yellowbird</b>			
Belt .....	806		6827
<b>PROFESSIONAL HARDWARE</b>			
<b>216-310</b>			
Drive .....	7540190		6839
<b>216-405</b>			
Tine .....	7540195		6854
Traction .....	7540109		6843
<b>218-200; 218-250</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>218-300; 218-350; 218-360; 828-5; 829-6; 829-7; 829-8</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>830-6</b>			
Belt .....	7540103		6827
<b>849-8</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>8248-0</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>8248-5; 8248-6; 8248-7</b>			
Drive .....	7540196		6830
<b>8248-9</b>			
Forward .....	7540103		6827
Reverse .....	7540121		6831
<b>8249-1; 8249-2; 8249-3</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>8249-4</b>			
Tine .....	7540192		6834
<b>8249-7; 8249-8</b>			
Drive .....	7540216		6729

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PROFESSIONAL HARDWARE - Continued</b>			
<b>8250-3</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>8250-5</b>			
Drive .....	7540192		6834
<b>8250-6; 8250-7; 8250-8</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>8251-0; 8251-1; 8251-2; 8251-3</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>8251-4; 8251-5; 8251-6; 8251-7; 8251-8</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>8251-9</b>			
Forward .....	7540103		6827
Reverse .....	7540121		6831
<b>8253-1</b>			
Forward .....	7540438		6851
Reverse .....	7540155		6509BR
<b>8255-2</b>			
Reverse .....	7540158		6935
<b>8256-3</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR

**ROOT**

<b>CT-3; CT-4; CT-5</b>			
Drive .....	12278		6848
<b>TG 3.5; TG 5</b>			
Drive .....	13370		6820

**ROPER**

<b>D300</b>			
Drive .....	9179R		6739
<b>D500; D550</b>			
Eng. To J.S. ....	4833H		6841
<b>D2110AR; D2117AR; D2117AW; D2118AR; D3000AR; D3000BR; D3000CR</b>			
Drive .....	9179R		6739
<b>D3217AR; D3218AR; D3218BR</b>			
Drive .....	9180R		6841
<b>D3611; D3611AR</b>			
Drive .....	9179R		6739
<b>D5000AR; D5211; D5211A; D5211AR; D5219AR</b>			
Drive .....	9180R		6841
<b>D5321A; D5321AR; D5500AR; D5500AT; D5500GR</b>			
Forward .....	4833H		6841
Reverse .....	2614J		6744
<b>D8531AR</b>			
Drive .....	4897H1		6837
<b>D9500AR</b>			
Forward .....	4833H		6841
Reverse .....	2614J		6744
<b>D32188R</b>			
Drive .....	9180R		6841
<b>D44135; D44135R</b>			
Drive .....	1071249		6850
<b>D44152; D44152R1</b>			
Drive .....	7140R		6840
<b>D54135R</b>			
Drive .....	1071249		6850
<b>D54252R1</b>			
Drive .....	7140R		6840

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>D5500AT</b>			
Drive .....	9180R		6841
<b>D55006R</b>			
Forward .....	4833H		6841
Reverse .....	2614J		6744
<b>D84351R1; D84351RO; D84361</b>			
Drive .....	4897H1		6837
<b>DE361</b>			
Drive .....	9179R		6739
<b>DE532</b>			
Forward .....	4833H		6841
Reverse .....	2614J		6744
<b>DE853</b>			
Drive .....	4897H1		6837
<b>DE5320AT; DE8531A</b>			
Forward .....	4833H		6841
Reverse .....	2614J		6744
<b>DE36108T</b>			
Drive .....	9179R		6739
<b>E1228AR</b>			
Drive .....	584J		6736
<b>J5000AT; J5000BR; J5000BT; J5000CR</b>			
Tine .....	9180R		6842
Trans. ....	102143X		6853
<b>J5000ER</b>			
Belt .....	102143X		6853
<b>P5500DR</b>			
Forward .....	26141		6745
Reverse .....			6841
<b>RT150FR</b>			
Belt .....	102143X		6853
<b>TR150FR</b>			
Drive .....	102143X		6853

**ROTO-HOE**

<b>148-5</b>			
Belt .....			6845
<b>148-CD</b>			
High Speed Drive .....	1081		6846
Low Speed Drive .....	1080		6851
<b>148-H</b>			
Belt .....			6845
<b>190CD</b>			
Belt .....	1543		6847
<b>190H</b>			
Belt .....	4059		6849
<b>220</b>			
Belt .....			6843
Drive .....	2480		6848
<b>904</b>			
Forward .....	1400		6846
Reverse .....			6837
<b>910</b>			
Eng. To J.S. ....	5065		6849
Front Mount .....	4075		6835
J.S. To Traction; W/33 1/2" Belt O.C. ....	5051		3V335
J.S. To Traction; W/35 1/2" Belt O.C. ....			3V355
Rear Mount .....	4076		6865
Secondary .....			6961
<b>910-2</b>			
Eng. To J.S. ....	5065A		6848
<b>990</b>			
Drive .....	5065A		6848
Eng. To J.S.; W/8 H.P. Eng. ....			6843
Trans. ....	5051		3V335



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROTO-HOE - Continued</b>			
<b>990-4</b>			
Eng. To J.S. ....	5065B		6844
<b>990-5</b>			
Eng. To J.S. ....	5065D		6845
Main Drive .....	5065B		6844
Rear Mount .....	1542D		6959
<b>990ZS</b>			
Main Drive; W/B. & S. 5 H.P. Eng. ....			6845
Main Drive; W/Kohler 8 H.P. Eng. ....			6843
<b>SP</b>			
High Speed Drive .....			6837
Low Speed Drive .....			6843
<b>SPR</b>			
Belt; W/43" Belt O.C. ....	2430		6843
Belt; W/54" Belt O.C. ....	2540		6854
<b>ROTOTILLER</b>			
<b>11; 11A</b>			
Belt .....	151	2333	
<b>23</b>			
Belt; W/34" Belt O.C. ....	137		6834
Belt; W/39" Belt O.C. ....	112		6839
<b>98</b>			
Belt .....	28232		6826
<b>105</b>			
Belt .....	28141		6825
<b>111</b>			
Belt .....	28151	2333	
<b>123</b>			
Belt .....	28137		6834
<b>133A</b>			
Belt; W/34" Belt O.C. ....	28137		6834
Belt; W/39" Belt O.C. ....	28112		6839
<b>T2</b>			
Belt; W/33" Belt O.C. ....	RJ151		6833
Belt; W/37" Belt O.C. ....			6837
<b>T3</b>			
Belt; W/34" Belt O.C.; Ser. No. 2747 & After .....	137		6834
Belt; W/37" Belt O.C.; Ser. No. 2746 & Before .....			6837
Belt; W/38" Belt O.C.; Ser. No. 2747 & After .....	138		6838
Belt; W/41" Belt O.C.; Ser. No. 2746 & Before .....	RJ124		6841
<b>SEARS ROEBUCK</b>			
<b>247.296650; 247.296651</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>247.296730; 247.296750; 247.296751</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>247.297650</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>247.297730; 247.297750</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>247.297780</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>247.298610; 247.298611; 247.298612;</b>			
<b>247.298620</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>247.298710; 247.298711; 247.298712</b>			
Forward .....	7540255		6837

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>247.298710; 247.298711; 247.298712 - Continued</b>			
Reverse .....	7540189		6844
<b>247.298750</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>247.298760</b>			
Drive .....	7540231		6828
Variable Speed .....	7540232		6820
<b>247.298770</b>			
Drive .....	7540224		6926
Variable Speed .....	7540221		6952
<b>247.298780; 247.298790</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>247.299770; 247.299771</b>			
Drive .....	7540224		6926
Variable Speed .....	7540221		6952
<b>247.299780</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>247.880800; 247.880910</b>			
Drive .....	7540196		6830
<b>359.63000; 359.63001</b>			
Drive .....	1108536		6927
<b>636.299950</b>			
Drive .....	08521220040		6941
<b>785.14000; 785.14500</b>			
Drive .....	509548		6829
<b>785.14501</b>			
Drive .....	507750		6828
<b>785.21300</b>			
Drive .....	J2210		6821
<b>785.29905X</b>			
Reverse .....	513857		6741
<b>785.50170; 785.50200; 785.50210</b>			
Drive .....	J2210		6821
<b>785.50300</b>			
Drive .....	501089		6830
<b>785.50302</b>			
Drive .....	J2390		6839
<b>785.50321</b>			
Belt; W/17" Belt O.C. ....			6817
Belt; W/19" Belt O.C. ....			6819
Drive .....	J2300		6830
<b>785.50340</b>			
Drive .....	J2390		6839
<b>785.50341</b>			
Belt; W/17" Belt O.C. ....			6817
Belt; W/19" Belt O.C. ....			6819
Drive .....	J2300		6830
<b>785.50360</b>			
Drive .....	J2300		6830
<b>785.50361; 785.50370; 785.50371</b>			
Belt; W/17" Belt O.C. ....			6817
Belt; W/19" Belt O.C. ....			6819
Drive .....	J2300		6830
<b>785.50400; 785.50410</b>			
Drive .....	J2300		6830
<b>785.50440</b>			
Belt; W/17" Belt O.C. ....			6817
Belt; W/19" Belt O.C. ....			6819
Drive .....	J2300		6830

Lawn & Garden Equipment



**TILLERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
785.50450 Drive ..... STD304490			6849
785.50470 Drive ..... J2350			6835
785.50570 Belt; W/17" Belt O.C. ....			6817
Belt; W/19" Belt O.C. ....			6819
785.50571 Belt; W/17" Belt O.C. ....			6817
Belt; W/19" Belt O.C. ....			6819
Drive ..... J2300			6830
785.50580 Belt; W/17" Belt O.C. ....			6817
Belt; W/19" Belt O.C. ....			6819
785.50606; 785.50630; 785.50650; 785.50651 Drive ..... 511227			6741
785.50690 Drive ..... J2300			6830
785.50691; 785.50692 Drive ..... 511227			6741
785.50701 Forward ..... 501089			6830
Reverse ..... 501330			6831
785.50720; 785.50721; 785.50722; 785.50723; 785.50724; 785.50725; 785.50726 Drive ..... J2300			6830
785.50741 Belt; W/17" Belt O.C. ....			6817
Belt; W/19" Belt O.C. ....			6819
785.50751; 785.50761 Belt; W/17" Belt O.C. ....			6817
Belt; W/19" Belt O.C. ....			6819
Drive ..... J2300			6830
785.50770 Belt; W/17" Belt O.C. ....			6817
Belt; W/19" Belt O.C. ....			6819
785.50900 Drive ..... J2300			6830
785.50901 Drive ..... STD304300			6830
785.50930 Drive ..... J2410			6841
785.52901 Drive ..... J2300			6830
785.262800 Drive; W/26" Belt O.C. ....			6826
Drive; W/35" Belt O.C. .... STD304350			6835
Drive; W/55" Belt O.C. .... 513727			6855
785.290020 Reverse ..... 507023			6739
785.290025 Drive ..... 513957			6723
Reverse ..... 513857			6741
785.290030 Drive ..... 511227			6741
785.290035 Drive ..... 513957			6723
785.290045; 785.290046; 785.290050; 785.290060; 785.290065 Drive ..... 511227			6741
785.290071 Reverse ..... 513857			6741
785.290075 Drive ..... 511227			6741

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
785.290245; 785.290255 Forward ..... 511192		2330	
Reverse ..... 511193			6733
785.291020 Drive ..... 513957			6723
785.291040; 785.291050; 785.291060; 785.291070 Drive ..... 511227			6741
785.291250; 785.291270; 785.291350; 785.291370; 785.292050; 785.292060 Reverse ..... 513857			6741
785.293040 Drive ..... 513957			6723
785.293050 Reverse ..... 513857			6741
785.293060 Drive ..... 513957			6723
Reverse ..... 513857			6741
785.294050; 785.294060; 785.294350; 785.294450; 785.295050; 785.295060; 785.295350; 785.296020; 785.296021; 785.296030 Reverse ..... 513857			6741
785.296160; 785.296350; 785.296351; 785.296352 Reverse ..... 513857			6741
785.298030; 785.298031 Belt ..... STD303390			6739
785.298040; 785.298041; 785.298050; 785.298060 Drive ..... 511227			6741
785.298140; 785.298150 Forward ..... 510271			6735
Reverse ..... 510228			6736
785.298240 Drive ..... STD304390			6839
785.298340 Drive ..... 511227			6741
785.299030 Belt ..... STD303390			6739
785.299040 Drive ..... 511227			6741
785.299050 Belt ..... 508774			6741
Drive ..... 511227			6741
785.299060 Belt ..... 508774			6741
785.299140; 785.299150 Forward ..... 511192		2330	
Reverse ..... 511193			6733
785.503401 Drive ..... J2300			6830
917.29481 Drive ..... 4897H1			6837
917.29913; 917.29915 Drive ..... 24732			6852
917.62401; 917.62405; 917.62406; 917.62407 Drive ..... 4897H1			6837
917.291480; 917.291482 Drive ..... 9180R			6841
917.291580 Drive ..... 4897H1			6837



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.292000 Drive .....	9180R		6841
917.292040; 917.292041 Drive .....	132801		6639BR
917.292200 Drive .....	9179R		6739
917.292300; 917.292301; 917.292302; 917.292350; 917.292352; 917.292380; 917.292381; 917.292390; 917.292391; 917.292392 Drive .....	9180R		6841
917.292393; 917.292394 Drive .....	9180R		6841
917.292400; 917.292401; 917.292402; 917.292403; 917.292450; 917.292460 Forward .....	133035		6841
Reverse .....	2614J		6744
917.292480; 917.292481 Drive .....	9180R		6841
917.292490; 917.292491; 917.292492; 917.292493 Forward .....	133035		6841
Reverse .....	2614J		6744
917.292560; 917.292580 Drive .....	4897H1		6837
917.293180 Drive .....	132801		6639BR
917.293200 Drive .....	132672		6853
917.293202; 917.293300; 917.293310; 917.293320 Drive .....	132801		6639BR
917.293340 Drive .....	138399		6859
917.293400; 917.293480; 917.293482; 917.293483; 917.293484; 917.293490; 917.293491; 917.293492; 917.293493 Drive .....	132801		6639BR
917.293560; 917.293570; 917.293580 Drive .....	4897H1		6837
917.293650; 917.293970; 917.294250; 917.294260; 917.294270; 917.294480; 917.294481; 917.294482; 917.294483 Drive .....	132801		6639BR
917.294560; 917.294561; 917.294580 Drive .....	4897H1		6837
917.295350; 917.295351; 917.295352; 917.295360 Drive .....	9180R		6841
917.295450; 917.295451; 917.295460 Forward .....	133035		6841
Reverse .....	2614J		6744
917.295550; 917.295551; 917.295552; 917.295553; 917.295554 Drive .....	132672		6853
917.295560; 917.295561 Drive .....	4897H1		6837
917.295562 Drive .....	STD324370		6837
917.295580; 917.295581; 917.295582; 917.295590; 917.295591 Drive .....	4897H1		6837

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.295651; 917.295652; 917.295653; 917.295660; 917.295661; 917.295670 Drive .....	132801		6639BR
917.295780 Drive .....	4897H1		6837
917.295850; 917.295851; 917.295852; 917.295853 Drive .....	132801		6639BR
917.296540; 917.296541 Drive .....	7140R		6739
917.296580 Drive .....	4897H1		6837
917.297520 Drive .....	9179R		6739
917.297550 Drive .....	9180R		6841
917.297580 Drive .....	4897H1		6837
917.298120 Drive .....	584J		6736
917.298130; 917.298131; 917.298132 Drive .....	9179R		6739
917.298140; 917.298141; 917.298142 Drive .....	9180R		6841
917.298160; 917.298161 Forward .....	4833H		6841
Reverse .....	2614J		6744
917.298230; 917.298231; 917.298232 Drive .....	9179R		6739
917.298240; 917.298241 Drive .....	9180R		6841
917.298242 Drive .....	9179R		6739
917.298350; 917.298411 Drive .....	9180R		6841
917.298520 Drive .....	9179R		6739
917.298540; 917.298541; 917.298550; 917.298551 Drive .....	9180R		6841
917.298560; 917.298570; 917.298580 Drive .....	4897H1		6837
917.299151; 917.299252 Drive .....	102143X		6853
917.299330; 917.299331; 917.299332; 917.299333 Drive .....	9179R		6739
917.299340 Drive .....	9180R		6841
917.299360 Forward .....	4833H		6841
Reverse .....	2614J		6744
917.299362 Forward .....	STD324410		6841
Reverse .....	2614J		6744
917.299370 Drive .....	9180R		6841
917.299380 Forward .....	4833H		6841
Reverse .....	2614J		6744
917.299381; 917.299382 Forward .....	STD324410		6841
Reverse .....	2614J		6744

Lawn & Garden Equipment

**TILLERS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
917.299430			
Drive .....	9179R		6739
917.299440; 917.299441; 917.299442			
Drive .....	9180R		6841
Reverse .....	2614J		6744
917.299450; 917.299460			
Forward .....	4833H		6841
Reverse .....	2614J		6744
917.299461			
Forward .....	STD324410		6841
Reverse .....	2614J		6744
917.299550; 917.299551; 917.299552;			
917.299560			
Drive .....	8377J		6859
917.299570; 917.299580			
Belt; W/37" Belt O.C. ....	4897H1		6837
Belt; W/82" Belt O.C. ....	5091H		6982
917.299590; 917.299591; 917.299592			
Drive .....	8377J		6859
917.299640; 917.299641; 917.299642			
Traction .....	102143X		6853
917.299651			
Drive .....	9180R		6841
917.299660; 917.299661; 917.299662;			
917.299680; 917.299681; 917.299682			
Drive .....	4376J		6849
Tine .....	4454J		6864
917.299760; 917.299762			
Drive .....	8377J		6859
<b>SENSATION</b>			
44S2; 46D5; 46T5			
Drive .....	153401		6848
<b>SENTRY</b>			
030-9			
Belt .....	7540216		6729
100-6; 100-7; 100-8			
Belt .....	7540103		6827
100-9			
Belt .....	7540196		6830
200-3			
Forward .....	7540107		6830
216-310			
Reverse .....	7540106		6825
Tine .....	7540190		6839
320-063			
Belt .....	7540190		6839
350-6			
Forward .....	7540104		6832
Reverse .....	7540103		6827
355-1; 355-2			
Forward .....	7540121		6831
Reverse .....	7540146		6833
355-3			
Forward .....	7540177		6832
Reverse .....	7540146		6833
355-4; 355-5; 355-6; 355-7; 355-8; 355-9;			
355-063			
Forward .....	7540154		6837
Reverse .....	7540189		6844
380-3			
Belt; W/35" Belt O.C. ....	7540158		6935
380-4; 385-4			
Belt .....	7540192		6834

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SENTRY - Continued</b>			
385-6; 385-7; 385-8; 385-9; 385-063			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>SIMPLICITY</b>			
073			
Drive .....	174883		6834
107; 233			
Forward .....	174883		6834
Reverse .....	176393		6737
330			
Drive .....	118225		6827
336			
Drive .....	118312		6834
360; 411			
Drive .....	118225		6827
413RT			
Drive .....	2029748	2338	
512			
Drive .....	118225		6827
516RT			
Forward .....	2027168		6834
Reverse .....	2029789		6734
549			
Forward .....	161146		6834
Reverse .....	1667200		6834
552			
Drive .....	118312		6834
695			
Forward .....			6834
Reverse .....	1675704		6390
821RT			
Forward .....	2029829		6837
Reverse .....	2029828		6737
910			
Forward; W/34" Belt O.C. ....			6834
Forward; W/37" Belt O.C. ....	176917		6837
Reverse; W/34 1/2" Belt O.C. ....	1675704		6390
Reverse; W/37" Belt O.C. ....	176393		6737
936			
Drive .....	174883		6834
938; 965			
Forward .....	161146		6834
Reverse .....	1667200		6834
1600397			
Drive .....	174883		6834
1600400			
Forward .....	161146		6834
Reverse .....	1667200		6834
1600403			
Forward .....	176917		6837
Reverse .....	176393		6737
1690237			
Drive .....	118312		6834
1690238			
Forward .....	174883		6834
Reverse .....	172929		6733
1690239			
Forward .....	176917		6837
1690322			
Drive .....	1663009		6728
1690324			
Forward .....	174883		6834
Reverse .....	1667200		6834



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>1690803</b>			
Traction .....	1671788		6746
<b>1692876</b>			
Drive .....	1716765		6825
<b>1692877</b>			
Forward .....	1716766		6827
Reverse .....	1716759		6728
<b>1693207</b>			
Drive .....	1718544		6833
<b>1693704</b>			
Forward .....	1716766		6827
Reverse .....	1716759		6728
<b>1693705</b>			
Drive .....	1716765		6825
<b>1693847; 1693848</b>			
Forward .....	1716766		6827
Reverse .....	1722144		6731
<b>SNAPPER</b>			
<b>300T</b>			
Belt; W/51" Belt O.C. ....	11969		6851
<b>301T; 301TR; 401T; 401TR</b>			
Trans.; 1976 & Older .....	11969		6851
Trans.; 1977 & Newer .....	12249		6837
<b>500T; 501T; 501TC</b>			
Belt; W/51" Belt O.C. ....	11969		6851
<b>501TR (Plow); 501TRC (Plow)</b>			
Secondary .....	12249		6837
<b>2510; 5001</b>			
Belt; W/51" Belt O.C. ....	11969		6851
<b>B6003</b>			
Drive .....	20560		6850
<b>ICFR5004B; IR4002B; IR5003B; NIR5003B</b>			
Drive .....	15403		6848
<b>R-8002</b>			
Eng. To Tine .....	14353		6862
<b>R8002B; R8002BE</b>			
Drive .....	14353		6862
<b>Speed Reduction Kit</b>			
Reducer To Chain Drive .....	12249		6837
Tiller Attachment; W/Rider Hitch Kit .....	12561		6854
<b>T502B</b>			
Drive .....	14353		6862
<b>SPEIGEL</b>			
<b>212-355</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>212-370</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>212-380</b>			
Reverse .....	7540158		6935
<b>213-355</b>			
Belt .....	7540166		6962
<b>213-375</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>214-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>214-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SPEIGEL - Continued</b>			
<b>214-375</b>			
Forward .....	7540190		6839
Reverse .....	7540189		6844
<b>214-395</b>			
Reverse .....	7540158		6935
<b>216-100</b>			
Belt .....	7540196		6830
<b>216-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>216-395</b>			
Reverse .....	7540158		6935
<b>SPRINGFIELD</b>			
<b>60R; 60-RBBO; 60-RCBO; 60-RTC; 60-RTCR; 61SVT; 61-SVTR; 61-VT; 61-VTR; 325-R</b>			
Forward .....	60R20		6833
Reverse .....	60R15		6734
<b>425-R</b>			
Forward .....	60R20		6833
Reverse .....	60R15		6734
<b>TECO</b>			
<b>10-204; 10-208; 10-216</b>			
Belt .....	1110		6835
<b>10-228; 10-232</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>10-233</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>10-241</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>10-242</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>10-258; 10-270</b>			
Forward .....	4052		6855
Reverse .....	4051		6731
<b>10-357; 10-366</b>			
Belt .....	3866		6826
<b>10-370; 10-455; 10-456</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>10-457; 10-458</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>10-503; 10-511; 10-512; 10-515; 10-522; 10-523; 10-524; 10-525</b>			
Belt .....	1110		6835
<b>10-534; 10-539</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>6290</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>6457</b>			
Forward .....	4052		6855
Reverse .....	4051		6731
<b>6548-4; 6548-5</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>6550-4; 6550-5</b>			
Forward .....	2435		6837
Reverse .....			6739

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TECO - Continued</b>			
6552-4			
Belt .....	3866		6826
6652-5			
Forward .....	1110		6835
Reverse .....	6163		6737
6680			
Forward .....	4052		6855
Reverse .....	4051		6731
6681-4; 6681-5			
Forward .....	2435		6837
Reverse .....			6739
6682-4; 6683-5			
Forward .....	4052		6855
Reverse .....	4051		6731
6750-6			
Forward .....	1110		6835
Reverse .....	6163		6737
6751-6			
Forward; W/35" Belt O.C. ....	1110		6835
Forward; W/37" Belt O.C. ....	2435		6837
Reverse; W/37" Belt O.C. ....	6163		6737
Reverse; W/39" Belt O.C. ....			6739
6752-6; 6753-6			
Forward .....	2435		6837
Reverse .....			6739
6754-6			
Forward .....	4052		6855
Reverse .....	4051		6731
6800			
Forward .....	1110		6835
Reverse .....	6163		6737
6801			
Forward .....	2435		6837
Reverse .....			6739
6802			
Forward .....	1110		6835
Reverse .....	6163		6737
6803			
Forward .....	2435		6837
Reverse .....			6739
6804			
Forward .....	4052		6855
Reverse .....	4051		6731
6809; 6810			
Forward .....	1110		6835
Reverse .....	6163		6737
6811			
Forward .....	2435		6837
Reverse .....			6739
<b>TORO</b>			
073 Rotical			
Drive .....	118068		6834
107 Deluxe Rotical; 233 Super Rotical			
Forward .....	118068		6834
Reverse .....			6736
330 Supermatic Rotical			
Trans. ....	118225		6827
336 Rotical			
Forward; W/3 H.P. Eng. ....	118312		6834
360 Supermatic Rotical; 411 Supermatic Rotical; 512 Supermatic Rotical			
Trans. ....	118225		6827
38100; 38108; 38110; 38118			
Drive .....	27168		6943

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
38121; 38122; 38123			
Belt; W/43" Belt O.C. ....	27168		6943
Belt; W/48" Belt O.C. ....	27191		6948
58000			
Forward; W/33" Belt O.C. ....	70354		6833
Forward; W/34" Belt O.C. ....	70073		6834
Reverse .....	70074		6733
58007			
Drive .....	263340		6833
58010; 58013			
Forward; W/33" Belt O.C. ....	70354		6833
Forward; W/34" Belt O.C. ....	70073		6834
Reverse .....	70074		6733
58015			
Forward .....	70354		6833
Reverse .....	248940		6733
58070			
Forward .....	207159		6673BR
Reverse .....	208626		6727
58100			
Forward; W/33" Belt O.C. ....	70354		6833
Forward; W/34" Belt O.C. ....	70073		6834
Reverse; W/31" Belt O.C. ....	70074		6733
Reverse; W/33" Belt O.C. ....	70074		6733
58110; 58114			
Forward .....	70073		6834
Reverse .....	70074		6733
58116			
Forward .....	70073		6834
Reverse .....	248940		6733
58125			
Forward .....	70073		6834
Reverse .....	70074		6733
58150			
Tine .....	200554		6846
Traction .....	200555		6746
58170			
Belt .....	208527		6848
58200			
Forward; W/33" Belt O.C. ....	70354		6833
Forward; W/34" Belt O.C. ....	70073		6834
Reverse .....	70074		6733
58210; 58215; 58220			
Forward .....	70073		6834
Reverse .....	70074		6733
58226			
Drive; Ser. No. 600001 & After .....	263540		6834
Reverse; Ser. No. 600001 & After .....	263550		6390
58231			
Forward .....	70073		6834
Reverse .....	70074		6733
58235			
Forward .....	70073		6834
Reverse .....	248940		6733
58237			
Drive; Ser. No. 600001 & After .....	263540		6834
Reverse; Ser. No. 600001 & After .....	263550		6390
58307; 58336			
Drive .....	282990		6828
Golfmaster			
Hydro. Pump .....	27140	2390	
<b>TRACTOR SUPPLY</b>			
44-0304			
Forward; W/27" Belt O.C. ....	7540103		6827
Forward; W/32" Belt O.C. ....	7540104		6832
Reverse; W/27" Belt O.C. ....	7540103		6827





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TRACTOR SUPPLY - Continued</b>			
<b>44-0304 - Continued</b>			
Reverse; W/31" Belt O.C. ....	7540121		6831
<b>44-0307; 44-0308</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>44-0315</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>44-0318</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>44-0326</b>			
Forward; W/37" Belt O.C. ....	7540154		6837
Forward; W/62" Belt O.C. ....	7540166		6962
Reverse; W/44" Belt O.C. ....	7540189		6844
Reverse; W/62" Belt O.C. ....	7540166		6962
<b>44-0329</b>			
Forward; W/37" Belt O.C. ....	7540154		6837
Forward; W/39" Belt O.C. ....	7540190		6839
Reverse; W/40" Belt O.C. ....	7540155		6509BR
Reverse; W/44" Belt O.C. ....	7540189		6844
<b>44-0337</b>			
Drive .....	7540192		6834
<b>44-1890</b>			
Drive; W/O Reverse .....	7540103		6827
Forward; W/30" Belt O.C. ....	7540107		6830
Forward; W/32" Belt O.C. ....	7540104		6832
Reverse; W/25" Belt O.C. ....	7540106		6825
Reverse; W/27" Belt O.C. ....	7540103		6827
<b>212-370</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>213-355</b>			
Forward .....	7540177		6832
Reverse .....	7540146		6833
<b>213-375</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR
<b>214-355</b>			
Forward .....			6839
Reverse .....	7540189		6844
<b>218-405</b>			
Forward .....	7540109		6843
Tine .....	7540195		6854
<b>350-131</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>553</b>			
Forward .....	1110		6835
Reverse .....	6163		6737
<b>554</b>			
Forward .....	2435		6837
Reverse .....			6739
<b>TROY BILT</b>			
<b>21A-682J; 21AE682L; 21AE686N; 0360 Horse; 682J Horse; 2215-2228 Horse III</b>			
Forward .....	9245		6540BR
<b>5040</b>			
Reverse .....	50134		6679BR
<b>5040 Pony V</b>			
Forward .....	50134		6679BR
<b>5041</b>			
Reverse .....	50134		6679BR
<b>5041 Pony V</b>			
Forward .....	50134		6679BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TROY BILT - Continued</b>			
<b>5150</b>			
Reverse .....	50134		6679BR
<b>5150 Pony V</b>			
Forward .....	50134		6679BR
<b>5151</b>			
Reverse .....	50134		6679BR
<b>5151 Pony V</b>			
Forward .....	50134		6679BR
<b>5411</b>			
Reverse .....	50134		6679BR
<b>5411 Pony VI</b>			
Forward .....	50134		6679BR
<b>5511</b>			
Reverse .....	50134		6679BR
<b>5511 Pony VI</b>			
Forward .....	50134		6679BR
<b>6000-8811 Horse III; 10056 Horse III; 12055 Horse; 12056 Horse; 12057 Horse; 12058 Horse; 12059 Horse</b>			
Forward .....	9245		6540BR
<b>12060 Tuffy</b>			
Forward .....	55037		6723
<b>12064 Horse; 12068 Horse; 12069 Horse; 12070 Horse; 12071 Horse; 12074 Horse; 12075 Horse; 12080 Horse; 12081 Horse; 12082 Horse</b>			
Forward .....	9245		6540BR
<b>12083 Horse; 12087 Std Horse; 12087C Horse; 12088 Std Horse; 12088C Horse; 12089 Pro Horse; 12089C Horse; 12090 Pro Horse; 12090C Horse; 12153 Horse</b>			
Forward .....	9245		6540BR
<b>12155 Tuffy</b>			
Forward .....	55037		6723
<b>12168 Versatiller</b>			
Drive .....	1911323		6827
<b>12180 Bronco</b>			
Forward .....	1916657		6825
Reverse .....	1916658		6610BR
<b>12181 Pony; 12182 Pony; 12183 Pro Line</b>			
Forward .....	1909404		6824
Reverse .....	1916753		6609BR
<b>12185 Econo Horse</b>			
Forward .....	1909404		6824
Reverse .....	9022		6722
<b>12204 Big Red Horse</b>			
Forward .....	9245		6540BR
<b>12208 Super Tuffy</b>			
Forward .....	1916657		6825
<b>12209 Bronco; 12210 Super Bronco</b>			
Forward .....	1916657		6825
Reverse .....	1916658		6610BR
<b>12211 Pony; 12212 Pony</b>			
Forward .....	1909404		6824
Reverse .....	1916753		6609BR
<b>12217 Tuffy</b>			
Forward .....	1916657		6825
<b>15006 Junior; 15008 Pony; 15009 Pony</b>			
Forward .....	20565		6824
<b>15010 Econo Horse</b>			
Forward .....	1909404		6824
Reverse .....	9022		6722
<b>20458</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722

Lawn & Garden Equipment

TILLERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TROY BILT - Continued</b>			
<b>20458 Pony I</b>			
Forward .....	9201		6546BR
<b>20459</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722
<b>20459 Pony I</b>			
Forward .....	9201		6546BR
<b>20460</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722
<b>20460 Pony I</b>			
Forward .....	9201		6546BR
<b>20461</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722
<b>20461 Pony I</b>			
Forward .....	9201		6546BR
<b>20462</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722
<b>20462 Pony I</b>			
Forward .....	9201		6546BR
<b>20463</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722
<b>20463 Pony I</b>			
Forward .....	9201		6546BR
<b>20558</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722
<b>20558 Super Pony</b>			
Forward .....	9201		6546BR
<b>20559</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722
<b>20559 Super Pony</b>			
Forward .....	9201		6546BR
<b>20570</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722
<b>20570 Pony II</b>			
Forward .....	9201		6546BR
<b>20571</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722
<b>20571 Pony II</b>			
Forward .....	9201		6546BR
<b>50173; 50173 Junior II; 50204; 50204 Junior II</b>			
Forward .....	50134		6679BR
<b>Cultivator Plus</b>			
Drive .....	60070		6732
<b>E682L Horse</b>			
Forward .....	9245		6540BR
<b>Econo Horse</b>			
Forward .....	20565		6824
Reverse .....	9022		6722
<b>Gardenway H60</b>			
Drive; W/6 H.P. Eng. ....	1128		6473BR
<b>Horse; Horse I; Horse II</b>			
Drive; W/2-Speed Eng.; W/Dual Belts .....	11281		6473BR
Drive; W/2-Speed Eng.; W/Single Belt .....	1128		6473BR
Drive; W/4-Speed Eng. ....	9245		6540BR
<b>Junior</b>			
Forward; New Style; W/24" Belt O.C. ....	20565		6824

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TROY BILT - Continued</b>			
<b>Junior - Continued</b>			
Forward; Old Style; W/25" Belt O.C. ....	50161		6825
Reverse; Old Style; W/28" Belt O.C. ....	50134		6679BR
<b>Junior II</b>			
Forward .....	50134		6679BR
<b>Pony I; Pony II</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722
<b>Pony III</b>			
Forward .....	20565		6824
Reverse .....			6723
<b>Pony IV</b>			
Forward .....	20565		6824
<b>Pony P-50; Pony P-51E</b>			
Forward .....	9201GD		6824
Reverse; W/22" Belt O.C. ....	9200GD		6822
Reverse; W/27" Belt O.C. ....	9095		6727
<b>Pony V</b>			
Forward .....	20565		6824
Reverse .....	50134		6679BR
<b>Pony VI</b>			
Reverse .....	50134		6679BR
<b>Roto-Ette</b>			
Drive .....	60070		6732
<b>Super Pony</b>			
Forward .....	9201		6546BR
Reverse .....	9200		6722
<b>TRU-TEST</b>			
<b>H45 Gardenway</b>			
Drive; W/4 1/2 H.P. Eng. ....	1128		6473BR
<b>TT66-5</b>			
Forward .....	10737		6831
Reverse .....	10737		6831
<b>UNICO</b>			
<b>10-308-08</b>			
Belt .....	1526		6822
<b>100-015</b>			
Drive .....	7540103		6827
<b>5021-71; 5021-81</b>			
Forward .....	7540216		6729
<b>5031-41</b>			
Drive .....	7540192		6834
<b>5031-61</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>5032-51</b>			
Drive .....	7540192		6834
<b>5032-61</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>5033-01 Turf-Til; 5033-81 Turf-Til; 5033-91 Turf-Til</b>			
Forward .....	7540216		6729
<b>5041-71</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>5050-01 Turf-Til; 5050-91 Turf-Til</b>			
Drive .....	7540224		6926
Variable Speed .....	7540221		6952
<b>5051-01 Turf-Til; 5051-41 Turf-Til; 5051-51 Turf-Til; 5051-61 Turf-Til; 5051-71 Turf-Til; 5051-81 Turf-Til; 5051-91 Turf-Til</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>UNICO - Continued</b>				<b>WESTERN AUTO - Continued</b>			
5052; 5052-1				2XC3337-63			
Forward; 1971 .....	7540121		6831	Belt .....	1221		6726
Reverse; 1971 .....	7540146		6833	2XC3339			
5055; 5055-2; 5055-3; 5055-41				Belt .....			6842
Eng. To Variator .....	7540157		6928	2XC3427			
Variator To Trans. ....	7540158		6935	Belt .....	1205		6822
5056-01 Turf-Til				2XC3438			
Forward .....	7540154		6837	Belt .....			6837
Reverse .....	7540201		6841	2XC3439			
5056-41; 5056-51				Belt .....			6842
Drive .....	7540192		6834	2XC3542; 2XC3642			
5056-61 Turf-Til; 5056-71 Turf-Til; 5056-81 Turf-Til; 5056-91 Turf-Til				Belt .....			6830
Forward .....	7540154		6837	2XC6685; 2XC6690			
Reverse .....	7540201		6841	Forward .....	7540121		6831
5057-61				Reverse .....	7540146		6833
Forward .....	7540196		6830	2XC3227			
Reverse .....	7540106		6825	Belt .....	1205		6822
5058-81				2XF2875			
Forward .....	7540154		6837	Belt .....			6827
Reverse .....	7540201		6841	2XF3139			
5059-81				Belt .....			6873
Eng. To Variator .....	7540232		6820	3X2010			
Variator To Drive .....	7540231		6828	Drive; W/O Reverse .....	1110		6835
5081				Forward .....	7540154		6837
Forward .....	7540154		6837	Reverse .....	7540189		6844
Reverse .....	7540155		6509BR	3X2020			
5081-01; 5081-71; 5081-81; 5081-91; 5082-01 Turf-Til				Forward .....	1110		6835
Drive .....	7540220		6927	Reverse .....	6163		6737
Variable Speed .....	7540221		6952	3X2025 (MTD)			
5351; 5351-0; 5351-2; 5351-3; 5351-41				Forward .....	7540154		6837
Forward .....	7540107		6830	Reverse .....	7540189		6844
Reverse .....	7540106		6825	3X2030			
5352; 5352-1				Forward .....	1110		6835
Drive .....	7540103		6827	Reverse .....	6163		6737
5352-01 Turf-Til				3X2040			
Forward .....	7540196		6830	Reverse .....			6739
5352-2; 5352-3; 5352-41				3X2045			
Drive .....	7540103		6827	Lower Drive .....	26345		6830
5352-51 Turf-Til; 5352-61 Turf-Til; 5352-71 Turf-Til; 5352-81 Turf-Til; 5352-91 Turf-Til				Upper Drive .....	26344		6819
Forward .....	7540196		6830	3XC2010			
<b>WESTERN AUTO</b>				Drive; W/O Reverse .....	1110		6835
2XC2005				Forward .....	7540154		6837
Drive .....	7540196		6830	Reverse .....	7540189		6844
2XC2933				3XC2025 (GIS)			
Belt .....	1212		6736	Forward .....	1110		6835
2XC2935				Reverse .....	6163		6737
Belt .....			6827	3XC2025 (MTD); 3XC2035 (MTD)			
2XC3027				Forward .....	7540154		6837
Belt .....	1205		6822	Reverse .....	7540189		6844
2XC3030; 2XC3031				3XC2036 (GIS)			
Belt .....	P54239		6829	Forward .....	1110		6835
2XC3033; 2XC3133				Reverse .....	6163		6737
Belt .....	P54242		6832	4X5705			
2XC3231				Belt .....	55019		6833
Belt .....			6831	4XC6290; 4XC6390			
2XC3233; 2XC3235				Belt .....	3660		6825
Belt .....			6832	4XC6475			
2XC3327				Belt .....	1526		6822
Belt .....	1205		6822	4XC6485			
				Forward .....	1110		6835
				Reverse .....	6163		6737
				4XC6495			
				Belt .....	1526		6822

TILLERS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
4XC6496 Belt .....	3660		6825
4XC6572 Forward .....	1110		6835
Reverse .....	6163		6737
4XC6575 Belt .....	1526		6822
4XC6585 Forward .....	1110		6835
Reverse .....	6163		6737
4XC6595 Belt .....	1526		6822
4XC6598; 4XC6685 Forward .....	1110		6835
Reverse .....	6163		6737
4XC6690 Forward .....	2435		6837
Reverse .....			6739
4XC6695 Belt .....	1526		6822
4XC6698 Forward .....	1110		6835
Reverse .....	6163		6737
4XC6699 Belt .....	3660		6825
4XC6772; 4XC6790; 4XC6798; 4XC6898 Forward .....	1110		6835
Reverse .....	6163		6737
4XC6899; 4XC6971 Forward .....	2435		6837
Reverse .....			6739
4XC6990 Forward .....	1110		6835
Reverse .....	6163		6737
4XC6995 Belt .....	1526		6822
4XC6999; 4XC7060; 4XF6899 Forward .....	2435		6837
Reverse .....			6739
4XF6971 Belt .....	9304		6829
4XF6995 Drive .....	1526		6822
Forward .....	2435		6837
Reverse .....			6739
4XF7071 Belt .....	9304		6829
218-100 Drive .....	7540103		6827
218-350; 218-360 Forward .....	7540104		6832
Reverse .....	7540103		6827
GIS62-146 Belt .....	9304		6829
GIS2000 Belt .....	33622		6727
GIS2010 Belt .....	1110		6835
GIS2020; GIS2025; GIS2030; GIS2035; GIS2036 Forward .....	1110		6835
Reverse .....	6163		6737
GIS2040 Forward .....	2435		6837
Reverse .....			6739

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
GIS2045 Lower Drive .....	26345		6830
Upper Drive .....	26344		6819
GIS2050; GIS2055; GIS2060 Belt .....	9304		6829
GIS2120A08; GIS2120A28; GIS2120A38; GIS2120A87; GIS2120A97; GIS2120B18; GIS2121A48 Traction .....	200555		6746
GIS2125 Traction .....	208526		6738
GIS2130A18; GIS2130A28; GIS2130A38 Traction .....	200555		6746
GIS2508 Eng. To Tiller .....	27093		6847
GIS6170; GIS6270 Belt .....	1110		6835
GIS6290; GIS6390 Belt .....	3660		6825
GIS6475; GIS6495 Belt .....	1526		6822
GIS6496 Belt .....	3660		6825
GIS6572 Forward .....	1110		6835
Reverse .....	6163		6737
GIS6575 Belt .....	1526		6822
GIS6585 Forward .....	1110		6835
Reverse .....	6163		6737
GIS6595 Belt .....	1526		6822
GIS6598; GIS6685 Forward .....	1110		6835
Reverse .....	6163		6737
GIS6695 Belt .....	1526		6822
GIS6698 Forward .....	1110		6835
Reverse .....	6163		6737
GIS6699 Belt .....	3660		6825
GIS6772; GIS6790; GIS6798; GIS6898 Forward .....	1110		6835
Reverse .....	6163		6737
GIS6899 Forward .....	2435		6837
Reverse .....			6739
GIS6971 Belt .....	9304		6829
GIS6990 Forward .....	1110		6835
Reverse .....	6163		6737
GIS6995 Belt .....	1526		6822
GIS6998 Forward .....	1110		6835
Reverse .....	6163		6737
GIS6999; GIS7060 Forward .....	2435		6837
Reverse .....			6739
GIS7071 Belt .....	9304		6829



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>MTD2002A88</b>			
Traction .....	7540190		6839
<b>MTD2002A98</b>			
Drive; W/37" Belt O.C. ....	7540255		6837
Drive; W/44" Belt O.C. ....	7540189		6844
Tine .....	7540190		6839
<b>MTD2005; MTD2005A57</b>			
Drive .....	7540196		6830
<b>MTD2010A57</b>			
Drive .....	7540154		6837
<b>MTD2022A; MTD2022A47; MTD2025A57; MTD2036; MTD2036A57</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>MTD2105A88</b>			
Forward .....	7540255		6837
Reverse .....	7540189		6844
<b>MTD3109A88; MTD3109A98</b>			
Belt; W/39" Belt O.C. ....	7540190		6839
Belt; W/43" Belt O.C. ....	7540109		6843
Tine .....	7540195		6854
<b>MTD4109A88; MTD4109A98</b>			
Tine .....	7540325		6857
<b>WHEEL HORSE</b>			
<b>7-1221</b>			
Drive; W/36" Belt O.C. ....	9430		6836
Drive; W/39" Belt O.C. ....	9431		6839
<b>7-1231; 7-1232</b>			
Drive .....	9151		6990
<b>RT666</b>			
Drive .....	1526		6822
<b>WHEELER</b>			
<b>WT3; WT55</b>			
Drive .....	107038		6836
<b>WHITE OUTDOOR PRODUCTS</b>			
<b>020</b>			
Drive .....	7540425		6726
<b>030; 031</b>			
Drive; W/29" Belt O.C. ....	7540216		6729
Drive; W/39" Belt O.C. ....	7540190		6839
<b>310</b>			
Tine .....	7540472		6812BR
<b>340</b>			
Drive .....	7540428		6842
<b>381</b>			
Tine; W/37" Belt O.C. ....	7540154		6837
Tine; W/41" Belt O.C. ....	7540201		6841
<b>390</b>			
Forward .....	7540429		6746
Reverse .....	7540428		6842
<b>402</b>			
Tine .....	7540207		6842
<b>403</b>			
Forward .....	7540109		6843
Reverse .....	7540190		6839
Tine .....	7540195		6854
<b>404; 405</b>			
Tine .....	7540109		6843
<b>406</b>			
Forward .....	7540109		6843
Reverse .....	7540190		6839
Tine .....	7540195		6854

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE OUTDOOR PRODUCTS - Continued</b>			
<b>412</b>			
Drive .....	7540268		6951
<b>420; 430</b>			
Drive .....	7540325		6857
<b>437; 447</b>			
Rear Tine .....	7540267		6859
<b>510</b>			
Belt .....	7540190		6839
<b>560</b>			
Forward .....	7540109		6843
Reverse .....	7540195		6854
<b>990-049</b>			
Forward .....	320005118		6830
Reverse .....	320005096		6825
<b>990-052</b>			
Drive .....	320020028		6834
<b>990-105</b>			
Tine; W/37" Belt O.C. ....	7540154		6837
Tine; W/41" Belt O.C. ....	7540201		6841
<b>990-148</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>990-199</b>			
Belt .....	7540216		6729
<b>991-105</b>			
Tine; W/37" Belt O.C. ....	7540154		6837
Tine; W/41" Belt O.C. ....	7540201		6841
<b>991-148</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>991-199</b>			
Belt .....	7540216		6729
<b>992-105 (500); 994-105</b>			
Tine; W/37" Belt O.C. ....	7540154		6837
Tine; W/41" Belt O.C. ....	7540201		6841
<b>994-199</b>			
Belt .....	7540216		6729
<b>994-318</b>			
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/51" Belt O.C. ....	7540268		6951
<b>994-319</b>			
Belt .....	7540190		6839
<b>994-377</b>			
Belt; W/43" Belt O.C. ....	7540253		6843
Belt; W/54" Belt O.C. ....	7540195		6854
<b>A430</b>			
Belt .....	7540267		6859
<b>RB300</b>			
Drive .....	9540216		6729
<b>RB500</b>			
Drive .....	9540428		6842
<b>RB550; RB650</b>			
Drive .....	9540434		6858
<b>Roto Boss 310</b>			
Belt .....	7540216		6729
<b>Roto Boss 500</b>			
Tine; W/37" Belt O.C. ....	7540154		6837
Tine; W/41" Belt O.C. ....	7540201		6841
<b>Roto Boss 510</b>			
Belt .....	7540190		6839
<b>Roto Boss 530</b>			
Drive .....	7540195		6854





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE OUTDOOR PRODUCTS - Continued</b>			
<b>Roto Boss 560</b>			
Forward .....	7540109		6843
Reverse .....	7540195		6854
<b>Roto Boss 580</b>			
Drive .....	7540325		6857
<b>Roto Boss 850</b>			
Belt .....	7540220		6927
<b>WHITE STORES</b>			
<b>86-59</b>			
Forward .....	7540177		6832
Reverse .....	7540146		6833
<b>86-61</b>			
Forward; W/37" Belt O.C. ....	7540154		6837
Forward; W/39" Belt O.C. ....	7540190		6839
Reverse; W/40" Belt O.C. ....	7540155		6509BR
Reverse; W/44" Belt O.C. ....	7540189		6844
<b>87-53</b>			
Drive .....	7540216		6729
<b>87-55</b>			
Drive; W/27" Belt O.C. ....	7540103		6827
Drive; W/30" Belt O.C. ....	7540196		6830
<b>87-59; 87-61</b>			
Forward; W/37" Belt O.C. ....	7540154		6837
Forward; W/39" Belt O.C. ....	7540190		6839
Reverse; W/40" Belt O.C. ....	7540155		6509BR
Reverse; W/44" Belt O.C. ....	7540189		6844
<b>87-62</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>87-63</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>87-64</b>			
Drive .....	7540192		6834
<b>87-65</b>			
Drive .....	7540232		6820
Tine .....	7540146		6833
Variable Speed .....	7540231		6828
<b>87-67</b>			
Drive .....	7540224		6926
Variable Speed .....	7540221		6952
<b>87-68</b>			
Drive .....	7540220		6927
Variable Speed .....	7540221		6952
<b>210-100</b>			
Drive .....	7540103		6827
<b>210-350; 210-360</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>212-100</b>			
Drive .....	7540103		6827
<b>212-355</b>			
Forward .....	7540121		6831
Reverse .....	7540146		6833
<b>212-375</b>			
Eng. To Variator .....	7540157		6928
Variator To Trans. ....	7540158		6935
<b>213-100</b>			
Drive .....	7540103		6827
<b>213-355</b>			
Forward .....	7540166		6962
<b>213-375</b>			
Forward .....	7540154		6837
Reverse .....	7540155		6509BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE STORES - Continued</b>			
<b>214-100</b>			
Drive .....	7540103		6827
<b>214-355</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>214-375</b>			
Forward .....	7540190		6839
Reverse .....	7540189		6844
<b>214-385</b>			
Drive .....	7540192		6834
<b>215-100</b>			
Drive .....	7540103		6827
<b>215-200</b>			
Forward .....	7540107		6830
Reverse .....	7540106		6825
<b>215-350</b>			
Forward .....	7540104		6832
Reverse .....	7540103		6827
<b>216-402</b>			
Tine .....	7540195		6854
Variable Speed .....	7540207		6842
<b>YARD MACHINES</b>			
<b>21A-035</b>			
Drive .....	7540216		6729
<b>21A-340</b>			
Drive .....	7540428		6842
<b>21A-390</b>			
Forward .....	7540428		6842
Reverse .....	7540429		6746
<b>21A-410; 21A-410A; 21A-412A; 21A-422B</b>			
Drive .....	7540438		6851
<b>21A-430; 21A-457A</b>			
Drive .....	7540434		6858
<b>YARD MARVEL</b>			
<b>F &amp; G 350; F &amp; G 515; F &amp; G Mini</b>			
Drive .....			6828
<b>Farm &amp; Garden</b>			
Drive .....	2073226		6826
<b>Mini Tiller</b>			
Belt .....			6828
<b>Renter</b>			
Drive .....	73226		②6826
<b>Renters 4K; Renters 5B</b>			
Drive .....	2073226		6826
<b>YARD-MAN</b>			
<b>21A-447; 21A-448A; 21A-458A</b>			
Drive; W/58" Belt O.C. ....	7540434		6858
Drive; W/59" Belt O.C. ....	7540267		6859
<b>211-031</b>			
Drive .....	7540216		6729
<b>211-430</b>			
Drive .....	7540325		6857
<b>211-700</b>			
Drive .....	7540190		6839
<b>5010-0; 5010-1; 5020-0; 5020-1; 5020-4;</b>			
<b>5030-0; 5030-1; 5030-4</b>			
Forward .....	40041		6840
Reverse .....	40207		6845
<b>5120-2-6; 5130-2-6</b>			
Drive .....	165176		6850
<b>21030-0; 21030-1; 21030-8; 21030-9</b>			
Drive .....	7540216		6729

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD-MAN - Continued</b>			
<b>21310</b>			
Drive .....	7540190		6839
<b>21398-1</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>21402</b>			
Belt; W/43" Belt O.C. ....	7540109		6843
Belt; W/54" Belt O.C. ....	7540195		6854
<b>21404</b>			
Belt; W/43" Belt O.C. ....	7540253		6843
Belt; W/54" Belt O.C. ....	7540195		6854
<b>21405-0; 21405-1; 21405-8; 21405-9</b>			
Primary Drive .....	7540224		6926
Secondary Drive .....	7540221		6952
<b>21406</b>			
Belt; W/39" Belt O.C. ....	7540190		6839
Belt; W/43" Belt O.C. ....	7540109		6843
Belt; W/54" Belt O.C. ....	7540195		6854
<b>21408-0; 21408-1; 21408-8; 21408-9; 21409-0;</b>			
<b>21409-1</b>			
Primary Drive .....	7540220		6927
Secondary Drive .....	7540221		6952
<b>21412; 21418</b>			
Belt; W/27" Belt O.C. ....	7540220		6927
Belt; W/51" Belt O.C. ....	7540268		6951
<b>21700-0; 21700-01</b>			
Drive .....	7540190		6839
<b>21705-0; 21705-1; 21705-8; 21705-9</b>			
Forward .....	7540154		6837
Reverse .....	7540189		6844
<b>21750-8; 21750-9</b>			
Forward .....	7540154		6837
<b>21755-0; 21755-1; 21755-8; 21755-9;</b>			
<b>21755-57</b>			
Forward .....	7540154		6837
Reverse .....	7540201		6841
<b>21756-0; 21756-8; 21756-9</b>			
Primary Drive .....	7540254		6819
Secondary Drive .....	7540231		6828
<b>YAZOO</b>			
<b>Cultivator</b>			
Tine; W/5 H.P. Eng. ....	205050		6850
<b>Gardener</b>			
Belt .....	205034		6834
<b>Master Gardener</b>			
Belt .....	205033		6833

Lawn & Garden Equipment



Manufacturers' Part Number Shown for Reference Only

Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ACE HARDWARE</b>			
<b>Edgers</b>			
200-600; 240-600; 241-600; 242-600; 243-600; 244-595; 244-600; 245-596; 246-596; 246-600			
Belt .....	7540142		6673BR
246-604; 247-600; 247-604; 248-600; 249-600			
Belt .....	7540142		6673BR
71359; 72774			
Blade .....	7540142		6673BR
<b>AER-EZE</b>			
<b>Aerators</b>			
Aerators			
Drive .....		3470	6947
<b>AGRIMETAL</b>			
<b>Vacuums</b>			
240 JD-2			
Blower .....			②6933
BW 300			
Blower .....			6944
BW 360			
Blower .....			④6953
Tuff Vac 5000 Gas			
Blower .....			②6942
Tuff Vac 5000 P.T.O.			
Blower .....			②6949
<b>AGWAY</b>			
<b>Edgers</b>			
82-0019; 82-0024; 82-1109; 82-3100; 82-3101; 240-600; 241-600; 242-600; 243-600; 244-600			
Blade .....	7540142		6673BR
<b>AIRCAP</b>			
<b>Edgers</b>			
618; 620; 674; 675; 676			
Belt .....	16301	2310	6831
B10			
Belt .....	10717		6730
<b>ALLIS-CHALMERS</b>			
<b>Compost Grinders</b>			
2024727			
Drive .....	14843		6829
2024730			
Drive .....	24615		6864
<b>AMERICAN HARDWARE</b>			
<b>Edgers</b>			
240-600; 241-600; 242-600; 243-600; 244-600; SSR596; SSR604			
Belt .....			6731
<b>ARIENS</b>			
<b>Compost Grinders</b>			
928001			
Belt .....	72062		6848
928002; 928003			
Belt .....	72060		6828
928004			
Belt .....	72071		6838
928005; 928007; 928008			
Belt .....	72060		6828

②Two Required ④Four Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>Compost Grinders - Continued</b>			
928010			
Belt .....	72062		6848
<b>P.T.O. Kits</b>			
731010			
Belt .....	072076		6835
731019			
Belt .....	072111		6834
<b>ATLAS</b>			
<b>Edgers</b>			
14-2000			
Belt .....			6732
A10; A10F			
Belt .....	1074		6829
B10			
Belt; 1973 .....			6732
C10; C10F			
Belt .....	1074		6829
<b>ATWATER STRONG</b>			
<b>Blower Sweepers</b>			
12KP Lo-Blo; 14KPT Lo-Blo			
Trans. ....	917		6735
16BPT			
Belt .....	1615	1410	6741
P.T.O. Pump			
Belt; W/28" Belt O.C.; W/25-50 H.P. Eng. ...	1087		3V280
<b>AUTOMOTIVE ASSOCIATES</b>			
<b>Edgers</b>			
242-600; 243-600; 244-600			
Belt .....	7540142		6673BR
<b>BACHTOLD BROTHERS</b>			
<b>Weed Cutters</b>			
B685 Mower			
Blade .....	B64		6967
<b>BAKER</b>			
<b>Chipper/Shredders</b>			
612			
Drive; Mfr. No. 9005612 .....	3080912		6928
912			
Drive; Mfr. No. 9007912, 9007913 .....	3080912		6928
<b>BEIL INDUSTRIES</b>			
<b>Cord Wood Saws</b>			
Lil Brute			
Drive .....			②6962
P.T.O. ....			②6951
<b>BILLY GOAT INDUSTRIES</b>			
<b>Aerators</b>			
AE401; AE401H; AE550; AE550H; AE551; AE551H			
Drive .....	360120		6843
<b>Blowers</b>			
F902SPH; F902SPS; F1302SPH; F1802SPV			
Drive .....	440215	1290	
QB1601SP			
Drive .....	830223		6834



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BILLY GOAT INDUSTRIES - Continued</b>				<b>BLUEBIRD - Continued</b>			
<b>Brush Cutters</b>				<b>Lawn Combers - Continued</b>			
BC2401H; BC2401HE; BC2401IC; BC2402H; BC2402HE; BC2403H; BC2403HEB; BC2403IC				720 Lawn Comber			
Blade Drive .....	500237		6488BR	Drive .....	0340		6938
Traction .....	500119		6827	C18; C183BTC; C184HTC; C185BDC; C185BFC; C185HDC; C185HFC; C1800DC; C1800FC; C1800TC			
<b>Power Rake/Overseeder</b>				Drive .....	54017		6933
CR550; CR550H; CR550HC				P18 Lawn Comber			
Drive .....	350207		6934	Drive; W/5.5 H.P. Eng. ....	54018		6934
OS552; OS552H; PR500; PR500H; PR550; PR550H				Drive; W/8 H.P. Eng. ....	0339		6936
Drive .....	350116		6936	P185BDC; P185BFB; P185BFC; P185HDC; P185HFB; P185HFC			
<b>Vacuums</b>				Drive .....	54018		6934
BG-10A; BG-50A; BG-60A; BG-60AI; BG-60P; BG-60PI				P188BDC; P188BFB; P188BFC			
Belt .....	800250	2320	6832	Drive .....	0339		6936
BG81SP; BG1002SP				P1800DC; P1800FB; P1800FC			
Drive .....	800250	2320		Drive; W/5.5 H.P. Eng. ....	54018		6934
KD512SP				Drive; W/8 H.P. Eng. ....	0339		6936
Drive .....	890586	2220		<b>Power Rake/Overseeder</b>			
KV600SP; KV650SPH				300RSC			
Drive .....	891026	1310		Belt .....	0339		6936
MV650SPH				300SC			
Drive .....	840066	1350		Belt .....	0314		6827
PB80; PB80P				410			
Belt; W/23" Belt O.C. ....	850314	2230	6823	Belt .....	0335	3350	6935
Belt; W/28" Belt O.C. ....	850313	2280	6828	420			
TKD512SP				Belt .....	0339		6936
Drive .....	890586	2220		510			
TKV650SPH				Belt .....	0335	3350	6935
Drive .....	891026	1310		520 Power Rake			
VQ802SPH; VQ902SPH; VQ1002SP				Drive .....	0339		6936
Drive .....	830223		6834	600			
<b>BLUE GRASS</b>				Belt .....	5028	3370	6937
<b>Edgers</b>				710			
W7-B600				Belt; W/36" Belt O.C. ....	0336	3360	6936
Drive .....	7540142		6673BR	Belt; W/37" Belt O.C. ....	0337	3370	6937
<b>BLUEBIRD</b>				720			
<b>Aerators</b>				Drive .....	0340		6938
424; 530A; 742; B424; B530A; H424; H424G; H530A; H530AG; H742				F20			
Drive .....	0336		6844	Belt; W/B. & S. 5 H.P. Eng. ....	0399		6936
H742G				Belt; W/B. & S. 7 H.P. Eng. ....	0340		6938
Drive .....	0336		6844	F20B			
<b>Lawn Combers</b>				Drive .....	0334		6831
120				F240			
Drive .....	0339		6936	Drive .....	0340		6938
120B				F400			
Drive .....	0334		6831	Belt .....	0333		6933
140				Drive .....	0341		6935
Drive .....	0333		6933	F405			
220				Belt .....	0333		6933
Drive .....	0340		6938	F407; F460			
240				Belt .....	0341	3350	6935
Drive .....	0341		6935	PR18; PR18B5FA; PR18B5NRA; PR18GH5NRA; PR18H5DA; PR18H5FA; PR18H5NRA; PR18NEFA; PR22; PR22B5FA			
405				Drive .....	100439	2370	
Drive .....	0333		6933	PR22B5FBA; PR22B5NRA; PR22B8FA; PR22B8NRA; PR22GH5NRA; PR22H5FA; PR22H5FBA; PR22H5NRA; PR22NEFA			
407				Drive .....	100439	2370	
Drive .....	0341		6935	TLC-240; TLC-720			
520 Lawn Comber				Eng. To Rotor .....	0340		6938
Drive .....	0339		6936				

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BLUEBIRD - Continued</b>			
<b>Seeders</b>			
120BLS Drive .....	0334		6831
120LS Drive .....	0339		6936
220LS Drive .....	0340		6938
520LS Drive .....	0339		6936
720LS Drive .....	0340		6938
F20BLS Drive .....	0334		6831
P185BDS; P185HDS Drive .....	54018		6934
P188BDS Drive .....	0339		6936
P1800DS Drive; W/5.5 H.P. Eng. .... Drive; W/8 H.P. Eng. ....	54018 0339		6934 6936
S22; S22B5DA; S22H5DA Drive .....	100439	2370	
<b>Seeders</b>			
Drive .....	0340		6938
<b>Sod Cutters</b>			
SC16 Blade .....			6828
SC18 Blade .....	3106		6826
<b>BOBCAT</b>			
<b>Edgers</b>			
E10-3B; E10-3C Belt .....	28004A		6831
<b>BOLENS</b>			
<b>Lift Kits</b>			
18703; 18704; 18705; 18706 Drive .....		2310	6831
18709 Belt .....			6832
<b>P.T.O. Kits</b>			
18309; 18309-04; 18309-05 Belt .....			6838
18318 Belt; W/B. & S. Eng. .... Belt; W/Tecumseh Eng. ....	1742385		6838 6372
<b>Starter Kits</b>			
22736-01; 23838-01 Belt .....	1708425		6828
23859 Belt .....	1713067	2290	6829
<b>BROUWER</b>			
<b>Sod Cutters</b>			
Mark 2 Blade Drive .....			6822
P.T.O. ....			6855
<b>BROWN</b>			
<b>Edgers</b>			
E104H Drive .....			②6848

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BROWN - Continued</b>			
<b>Edgers - Continued</b>			
Edge Master Drive .....	E-200-002		②6848
<b>BROYHILL</b>			
<b>Sprayer Equipment</b>			
1366D Belt; W/9 H.P. Eng. ....	5804	2340	6834
1674D Belt; W/16 H.P. Eng. ....	7108	2450	6845
1760 Agitator; For Model 1805B; W/3 H.P. Eng. ....	7128	2270	6827
Belt; For Model 1806C; W/1 H.P. Eng. ....	5812	2370	6837
Pump; For Model 1805B; W/3 H.P. Eng. ....	6535	2300	6830
1760BR Belt; For Model 1920A; W/3 H.P. Eng. ....	4681	2330	6833
1761C-2P-MA Agitator; W/1 H.P. Eng. ....	7128	2270	6827
Pump; W/1 H.P. Eng. ....	5812	2370	6837
1879 Belt; W/9 H.P. Eng. ....	5224		3V500
1956A Belt; W/8 H.P. Eng. ....			6842
1963B Belt; W/5, 8 H.P. Eng. ....	6980		6831
2000 Belt; W/8 H.P. Eng. ....	5759		B60
2042 Belt; W/8 H.P. Eng. ....	3279	3480	6948
2087A Belt; W/8 H.P. Eng. ....	5759		B60
2088A Belt; W/8 H.P. Eng. ....	6966	2220	6822
2093A Belt; W/16 H.P. Eng. ....	7081		3V800
<b>BUNTON</b>			
<b>Edgers</b>			
760; BLM; ET10 Blade .....	PG757	2300	6830
GM52 Blade .....	L643		6850
<b>CAMPBELL HAUSFELD</b>			
<b>Air Compressors</b>			
HL701000AJ Belt .....	BT004700AV	2390	6839
HL701100AJ Belt; W/39" Belt O.C. .... Belt; W/40" Belt O.C. ....	BT004700AV BT000400AV	2390 2400	6839 6840
HL701200AJ; HL701300AJ Belt .....	BT000400AV	2400	6840
HL701500AJ Belt .....	BT004700AV	2390	6839
HL701600AJ Belt; W/39" Belt O.C. .... Belt; W/40" Belt O.C. ....	BT004700AV BT000400AV	2390 2400	6839 6840
HL701700AJ Belt .....	BT000400AV	2400	6840
Power-Pro VT61100; Power-Pro VT610900; Power-Pro VT614801AJ Belt .....	BT003400AV	3490	6949

②Two Required





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CAMPBELL HAUSFELD - Continued</b>			
<b>Air Compressors - Continued</b>			
TF000821HA; TF000821VA; TF410821HA; TF410821VA; TF430821HA; TF430821VA; TF460352HA Belt .....	BT004302AV		6970
TK000821H; TK001221H; TK630821H; TK631221H; TK631281H Belt .....	BT004319AV		6981
<b>CAUDLE MFG. CO</b>			
<b>Edgers</b>			
60102 Belt; W/2 H.P. Eng. ....	6526	2300	6830
<b>CHAMPION</b>			
<b>Sprayer Equipment</b>			
CHAMPION 600 Belt .....		2450	6845
CHAMPION 701 Belt .....	745	2350	6835
<b>CHIP-IT INDUSTRIES</b>			
<b>Chippers</b>			
MC 180 P.T.O. ....			AX43
MC 260 P.T.O. ....			BX68
<b>Stump Grinders</b>			
Eliminator Pump .....			AX37
<b>CLASSEN MFG. CO.</b>			
<b>Aerators</b>			
400 Belt; W/Honda 3 1/2 H.P. Eng. .... Belt; W/Honda 5 H.P. Eng. ....			6939 6936
500 Belt; W/Honda 5 H.P. Eng. ....			6936
500ATC Belt; W/36" Belt O.C. .... Belt; W/38" Belt O.C. ....	VB1500ATC VB2500ATC		6936 6938
600 Belt .....	VB1600		6935
TA-19 P.T.O. ....			6946
<b>Sod Cutters</b>			
SC-18 Drive .....			6934
P.T.O. ....	B56		6959
<b>Weed Cutters</b>			
Weed Mower Belt .....			6931
<b>COAST TO COAST</b>			
<b>Edgers</b>			
240-600; 242-600; HEO-371-9 Belt .....	7540142		6673BR
<b>COLUMBIA PRODUCTS</b>			
<b>Edgers</b>			
242-295; 601-2; 601-3; 601-4 Belt .....	7540142		6673BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CRARY</b>			
<b>Chipper/Shredders</b>			
30; 50 Rotor .....	16081		6927
80; 85 Rotor .....	16043		6929
150 Rotor .....	16081		6927
180 Rotor .....	16043		6929
250 Rotor .....	16081		6927
280 Rotor .....	16043		6929
380 Rotor .....	17996		6829
500 Rotor .....	16000		ⓂBX62
510 P.T.O. ....	16021		ⓂBX46
554 P.T.O. ....	17055		ⓂBX56
580 Rotor .....	17996		6829
70030; 70050 Rotor .....	17829		6927
70080; 70085 Rotor .....	17830		6929
70150 Rotor .....	17829		6927
70180 Rotor .....	17830		6929
70250 Rotor .....	17829		6927
70380 Rotor .....	17996		6829
70500 Rotor .....	16000		ⓂBX62
70510 P.T.O. ....	16021		ⓂBX46
70554 P.T.O. ....	17055		ⓂBX56
<b>CUB CADET</b>			
<b>Edgers</b>			
603 Belt .....	7540142		6673BR
<b>DEVILBISS</b>			
<b>Air Compressors</b>			
TAM-5042; TAMV-5042 Belt; W/1 1/2 H.P. Eng. ....	JH1035		Ⓜ6863
TAN-5042; TANV-5042 Belt; W/2 H.P. Eng. ....			Ⓜ6865
TAO-5042 Belt; W/3 H.P. Eng. ....			Ⓜ6867
TAO-5050 Belt; W/3 H.P. Eng. ....			Ⓜ6981
TAOV-5042 Belt; W/3 H.P. Eng. ....			Ⓜ6867
TAOV-5050 Belt; W/3 H.P. Eng. ....			Ⓜ6981

ⓂTwo Required

**LAWN EQUIPMENT**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DEVILBISS - Continued</b>			
<b>Air Compressors - Continued</b>			
TAP-5050 Belt; W/5 H.P. Eng. .... UAG4			②6985
TAPE-5031 Belt; W/10 H.P. Eng. ....			②6981
TAPV-5050 Belt; W/5 H.P. Eng. ....			②6981
TAS-5050 Belt; W/7 1/2 H.P. Eng. ....			②6992
TDP-5050 Belt; W/5 H.P. Eng. .... UAG4			②6985
TDS-5050 Belt; W/7 1/2 H.P. Eng. ....			②6992
UAH-5020 Belt; W/1/4 H.P. Eng. ....			6842
UAK-5032 Belt; W/3/4 H.P. Eng. .... BT9004			6955
UAL-5042 Belt; W/1 H.P. Eng. .... BT9004			6955
UALE-5030 Belt; W/3 H.P. Eng. ....			6960
UAM-5044; UAMV-5044 Belt; W/1 1/2 H.P. Eng. .... BT9001			6859
UAN-5044 Belt; W/2 H.P. Eng. .... JH1035			6863
UANE-5031 Belt; W/8 H.P. Eng. ....			②6870
UANV-5044 Belt; W/2 H.P. Eng. .... JH1035			6863
UBHB-9010 Belt; W/1/4 H.P. Eng. .... BT9006			6836
UBJ-5012 Belt; W/1/2 H.P. Eng. ....			6944
UBK-5012 Belt; W/3/4 H.P. Eng. ....			6946
UDH-5020 Belt; W/1/4 H.P. Eng. ....			6844
UDJ-5031 Belt; W/1/2 H.P. Eng. ....			6855
UDK-5030 Belt; W/3/4 H.P. Eng. .... BT9004			6955
UDL-5012 Belt; W/1 H.P. Eng. ....			6844
UDL-5030 Belt; W/1 H.P. Eng. .... BT9004			6955
UDM-5013 Belt; W/1 1/2 H.P. Eng. ....			6854
UDM-5043 Belt; W/1 1/2 H.P. Eng. ....			6869
UDN-5013 Belt; W/2 H.P. Eng. ....			6855
UDN-5043 Belt; W/2 H.P. Eng. .... JH1035			6863
UDO-5043 Belt; W/3 H.P. Eng. ....			②6867
VAO-5050 Belt; W/3 H.P. Eng. ....			②6986
VAOV-5050 Belt; W/3 H.P. Eng. .... BT131			②6986
VAP-5050 Belt; W/5 H.P. Eng. .... UAG4			②6985

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DEVILBISS - Continued</b>			
<b>Air Compressors - Continued</b>			
VAPE-5030 Belt; W/10 H.P. Eng. ....			②6986
VAPV-5050 Belt; W/5 H.P. Eng. ....			②6981
VAS-5059 Belt; W/7 1/2 H.P. Eng. ....			②6992
VAS-5060 Belt; W/7 1/2 H.P. Eng. .... JK85			③69100
VAT-5060 Belt; W/10 H.P. Eng. .... JK85			③69100
VAV-5060 Belt; W/15 H.P. Eng. ....			③69100
VAVE-5060G Belt; W/30 H.P. Eng. .... BT119			⑥B100
VAW-5080 Belt; W/20 H.P. Eng. .... BT119			⑥B100
VAX-5080; VAX-5081 Belt; W/25 H.P. Eng. .... BT119			⑥B100
VDO-5050 Belt; W/3 H.P. Eng. ....			②6986
VDS-5059 Belt; W/7 1/2 H.P. Eng. ....			②6992
VDS-5060 Belt; W/7 1/2 H.P. Eng. .... JK85			③69100
VDT-5060 Belt; W/10 H.P. Eng. .... JK85			③69100
VDV-5060 Belt; W/15 H.P. Eng. ....			③69100
VDW-5080 Belt; W/20 H.P. Eng. .... BT119			⑥B100
VDX-5080; VDX-5081 Belt; W/25 H.P. Eng. .... BT119			⑥B100
<b>DIADEM</b>			
<b>Compost Grinders</b>			
312P3; 312W8; 312W10 Belt .....			6955
312W12 Belt .....			6954
Bush Chipper Belt; W/8, 12 H.P. Eng. .... 31216531		3530	6953
P.T.O. .... 31217956			6951
Clipper Belt; W/7 H.P. Eng. .... 31216531		3530	6953
<b>DR POWER EQUIPMENT</b>			
<b>Power Wagon</b>			
5.0 Powerwagon; Premier Powerwagon Drive .....	108971		A82
Pro Powerwagon Drive; Feb. 2007 & Newer .....	108971		A82
Drive; Jan. 2007 & Older .....			6884
Suburban Powerwagon Drive .....	108991		6838
<b>String Trimmer</b>			
Commercial Trimmer Drive .....	114431		6845
Compact Trimmer Drive .....		1390	

②Two Required ③Three Required ⑥Six Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DR POWER EQUIPMENT - Continued</b>			
<b>String Trimmer - Continued</b>			
Pro Trimmer; Pro-XL Trimmer; Self-Propelled Trimmer; Sprint Trimmer			
Drive .....	114431		6845
<b>DYNAMARK</b>			
<b>Edgers</b>			
85680; 87000; 87010; 87020			
Blade .....	32668		6833
53990100; 53990200; 53990300; 53990400			
Belt .....	2543		6828
A3009000			
Blade .....		2328	
<b>Sweepers</b>			
5365			
Belt .....	RP8096	2260	6826
P.T.O.; W/40" Belt O.C. ....	42035	1400	
79972; 79980; 79981			
Belt .....	8597	2220	6822
PS124			
Belt .....		2200	6820
PS928A			
Belt .....	RP8096	2260	6826
P.T.O.; W/40" Belt O.C. ....	42035	1400	
<b>ENVIROJET</b>			
<b>Aerators</b>			
RC387B			
Agitator .....	2600		6860
Pump .....			②3VX425
<b>EXMARK</b>			
<b>Power Rake/Overseeder</b>			
RA-50B			
Main Drive .....			6939
<b>FATE-ROOT-HEATH</b>			
<b>Lawn Mower Sharpeners</b>			
20			
Belt .....	J204	1270	6727
21A			
Belt .....	R192	2290	6829
150			
Belt .....	JD50	2250	6825
210			
Belt .....	R309	2380	6838
400; 410			
Belt .....	R308	2340	6834
900			
Belt; W/29" Belt O.C. ....	R192	2290	6829
Belt; W/37" Belt O.C. ....	R87	2370	6837
1040; 1070			
Belt .....	JD50	2250	6825
1300			
Belt; Domestic .....		2320	6832
Belt; Export .....	GD1407	2330	6833
<b>FELDMANN</b>			
<b>Aerators</b>			
1700; 1703; 1800; 2200; 2300MP			
Belt .....	1434		6728

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FIMCO, INC.</b>			
<b>Sprayer Equipment</b>			
25-80G			
Belt .....			6831
30-78FG			
Belt .....			6827
80-12; 80-22; 80-24			
Belt .....			6828
ES-121			
Belt .....			6831
<b>FIRESTONE</b>			
<b>Edgers</b>			
422-3-600; 422-5-600; Supreme 08-09-300-8; Supreme 08-09-300-9			
Blade .....	7540142		6673BR
<b>FOLEY</b>			
<b>Lawn Mower Sharpeners</b>			
1/2 H.P. Combination; 1/3 H.P. Standard			
Belt .....	370630	2300	6830
<b>GIANT VAC</b>			
<b>Power Rake/Overseeder</b>			
GT51			
Traction .....			6828
<b>Vacuums</b>			
59			
Belt .....			6735
1730			
Traction .....			6726
<b>GILSON</b>			
<b>Compost Grinders</b>			
30-200-01			
Blade .....	83EA335	3580	6958
30-201-01; 30-202-01; 30-300-01			
Drive .....	1434		6728
30-311-01			
Belt .....	14843		6829
88C			
Belt .....	1409	3520	6952
605			
Belt .....	14843		6829
707			
Belt .....	1409	3520	6952
808; 909			
Drive .....	1434		6728
4254			
Belt .....	14843		6829
54250			
Drive .....	1434		6728
54252			
Belt .....	1409	3520	6952
54253; 54254			
Belt .....	14843		6829
54255			
Drive .....	1434		6728
54260; 54261; 54262			
Belt .....	24615		6864
SG8A			
Drive .....	1434		6728
SGS			
Blade .....	83EA335	3580	6958

②Two Required

**LAWN EQUIPMENT**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GOODALL</b>			
<b>Edgers</b>			
10BT; 10LT			
Blade .....	W00667		6824
760			
Blade .....	W00657		6830
<b>GOOSSEN</b>			
<b>Blowers</b>			
BL-2000 P.T.O.			
P.T.O.; W/47" Belt O.C. ....			④6947
P.T.O.; W/53" Belt O.C. ....			④5VX530
<b>Vacuums</b>			
Rake-N-Vac			
Blower .....			④6946
<b>GRAINGER, W. W.</b>			
<b>Compost Grinders</b>			
3Z417			
Belt .....	26415		6864
<b>Edgers</b>			
3Z478A; 3Z478D			
Blade .....	7540142		6673BR
<b>Vacuums</b>			
3Z479A			
Belt .....	7540176	0230	
3Z479D			
Belt .....	7540219		6826
<b>GRAVELY</b>			
<b>Aerators</b>			
Proaire 27			
Drive .....	B54		6957
Pump .....			6939
<b>Chippers</b>			
Pro Chip 350			
Drive .....			②6958
Pro Chip 495			
Pump .....			6958
<b>HAHN</b>			
<b>Aerifiers</b>			
EA-3			
Drive; W/36" Belt O.C. ....		3360	6936
Drive; W/56" Belt O.C. ....		3560	6956
Multi-Pro 44			
Eng. To Chain Drive .....			TR28437
Eng. To Pump .....	4L390	2390	
TMV			
Eng. To Trans. ....	44D		AX43
<b>Power Rake/Overseeder</b>			
VCD-14 Varti-Cut			
Drive .....			6830
<b>HOGG</b>			
<b>Edgers</b>			
Edge-N-Trim Heavy Duty			
Blade; W/2, 3, 3.5 H.P. Eng. ....		2270	6827
E-Z Edge			
Blade .....		1240	6724
<b>HOMELITE</b>			
<b>Edgers</b>			
2 Cycle			
Blade .....		1240	6724

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HOMELITE - Continued</b>			
<b>Edgers - Continued</b>			
3 H.P.			
Blade; W/28" Belt O.C. ....		1280	6728
Blade; W/31" Belt O.C. ....		2310	6831
<b>Multi-Purpose Saws</b>			
MP38; MP88			
Belt .....	46068		3VX335
XL98A			
Drive .....	64498		6413BR
XL98D			
Belt .....	46068		3VX335
<b>HOMKO</b>			
<b>Edgers</b>			
53990200; 53990300; 53990400			
Drive .....	2543		6828
<b>HONDA</b>			
<b>Generators</b>			
E1500K1; E1500K3			
Belt; W/4.5 H.P. Eng. ....	012151		②A30
E1500K4			
Belt; W/5 H.P. Eng. ....	068851		6931
E2500K2; E2500K3			
Belt; W/6.8 H.P. Eng. ....	040206		②6832
E2500K4			
Belt; W/7 H.P. Eng. ....	047562		BX35
E3500K1; E3500K2			
Belt; W/10 H.P. Eng. ....	075624		6940
E4500K1			
Belt; W/10 H.P. Eng. ....	078838		BX36
ES3500			
Belt; W/8 H.P. Eng. ....	047562		BX35
ES3500K1; ES3500K2			
Belt; W/10 H.P. Eng. ....	075624		6940
ES4500K1			
Belt; W/10 H.P. Eng. ....	078838		BX36
<b>HUDSON</b>			
<b>Sprayer Equipment</b>			
42025; 47025			
Belt .....		2610	6861
<b>HUFFMAN</b>			
<b>Edgers</b>			
2796			
Blade .....	9657B	2390	6839
2797			
Blade .....	BE117	2270	6827
4796			
Blade .....	9657B	2390	6839
4797			
Blade .....	BE117	2270	6827
H5800			
Blade .....	9657B	2390	6839
<b>HUSQVARNA</b>			
<b>Edgers</b>			
LE359; LE389			
Drive .....			6833

②Two Required ④Four Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JACOBSEN</b>			
<b>Aerators</b>			
<b>T1224</b>			
Drive .....			Ⓢ6860
Hyd. Pump .....			6829
<b>Brooms</b>			
<b>81507</b>			
Broom .....	348720		6872
Drive .....	349079		6877
<b>Edgers</b>			
<b>5000; 50012</b>			
Belt .....	310119	2320	6832
<b>Eagle SN-TX1376</b>			
Belt .....			6831
<b>P.T.O. Kits</b>			
<b>59542; 59564; 59572</b>			
Drive .....	329207		6836
<b>59665</b>			
Drive .....	325074	2840	6884
<b>59669</b>			
Drive .....	342307	2860	6886
<b>59674</b>			
Drive .....	329253		6890
<b>59792; 59825; 59834; 59864</b>			
Blade .....	328821		6883
Mower .....	328891		6377
<b>GT Rear P.T.O.</b>			
Belt; W/Dual Belts .....	392445		Ⓢ6828
Belt; W/Single Belt .....	330675		6828
<b>Power Rake/Overseeder</b>			
<b>52010; 52101</b>			
Drive .....	314564		6829
<b>Seeders/Vericutters</b>			
<b>VA-24</b>			
Pump .....	366201		6829
<b>Sod Cutters</b>			
<b>11C</b>			
Belt .....	1024		6857
<b>Sweepers</b>			
<b>154</b>			
Trans. ....	349432		Ⓢ3V315
<b>720E; 720EHL</b>			
Eng. To Hyd. Pump .....	349006	3410	6941
<b>JOHN BEAN</b>			
<b>Sprayer Equipment</b>			
<b>2M Spartan; 3/Spartan; 3M/Spartan</b>			
Pump .....	1108472		6839
<b>4A; 4E; 4G</b>			
Pump .....			6848
<b>07</b>			
Agitator .....	1108540		6931
Pump .....	1107403		6862
<b>20MTB/Royal 20"</b>			
Agitator .....	1108553		6844
Pump; W/Wisconsin TF Eng. ....	1108430		6968
Pump; W/Wisconsin VE4 Eng. ....	1108426		6958
<b>25</b>			
Agitator; 1969 & Older .....	1108554		6945
Pump; W/Wisconsin THD Eng.; 1969 & Older .....	1250337		6867
Pump; W/Wisconsin VH4D Eng.; 1969 & Older .....	1261546		6965

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN BEAN - Continued</b>			
<b>Sprayer Equipment - Continued</b>			
<b>44</b>			
Agitator; W/100, 150 Gal. Tank .....	1108466		6833
Agitator; W/50 Gal. Tank .....	1108459		6828
Pump; W/100, 150 Gal. Tank .....	1107401		6855
Pump; W/50 Gal. Tank .....	1107400		6853
<b>48/Royal 20"</b>			
Agitator .....	1108577		6968
Pump; W/Wisconsin VE4 Eng. ....	1108426		6958
<b>48MT/Royal 20"; 48T/Royal 20"; 48TR/Royal 20"</b>			
Agitator .....	1108577		6968
Pump .....	1108426		6958
<b>66</b>			
Agitator .....	1108551		6942
Pump .....	1107407		6870
<b>70</b>			
Agitator .....	1108466		6833
Pump .....	1108429		6967
<b>1010</b>			
Agitator; W/150 Gal. Tank .....			6830
Agitator; W/200 Gal. Tank .....			6734
Agitator; W/300 Gal. Tank .....			6937
Pump .....	1278510		6862
<b>2020</b>			
Agitator; W/200 Gal. Tank .....			6831
Agitator; W/300 Gal. Tank .....	1108542		6933
Agitator; W/400, 500 Gal. Tank .....	1108543		6934
<b>2030; 2032; 3320</b>			
Pump; W/Electric Eng. ....	1108477		6844
Pump; W/Gas Eng. ....	1108484		6851
<b>J20</b>			
Agitator; W/200 Gal. Tank; W/Electric Start .....	1108469		6836
Agitator; W/200 Gal. Tank; W/Magneto Eng. ....	1108467		6834
Agitator; W/300 Gal. Tank; W/Magneto Eng. ....	1108454		6821
Agitator; W/400, 500 Gal. Tank .....	1108547		6938
<b>L1528-2</b>			
Pump; W/Electric Eng. ....	1108547		6938
Pump; W/Gas Eng. ....	1108484		6851
<b>N25</b>			
Pump; W/Wisconsin THD Eng.; 1969 & Older .....	1250337		6967
Pump; W/Wisconsin VH4D Eng.; 1969 & Older .....	1261546		6865
<b>N35</b>			
Agitator; 1969 & Older .....	1108567		6958
Pump; W/Wisconsin THD Eng.; 1969 & Older .....	1250337		6967
Pump; W/Wisconsin VH4D Eng.; 1969 & Older .....	1261546		6965
<b>JOHN DEERE</b>			
<b>Aerators</b>			
<b>Aercore 1000; Aercore 1500; Aercore 2000</b>			
Drive .....	MT3040		6794BR
<b>Air Compressors</b>			
<b>A75</b>			
Main Drive .....	TY4798		6837
<b>Edgers</b>			
<b>2</b>			
Blade .....	M47159	2295	
<b>2 H.P.</b>			
Blade .....	M47150	2295	
<b>3</b>			
Blade .....	M47159	2295	

ⓈTwo Required

LAWN EQUIPMENT



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>Edgers - Continued</b>			
3 H.P. Blade .....	M47150	2295	
3K Blade .....	M47159	2295	
4 H.P. Blade .....	M47150	2295	
M0036 Blade .....		2300	6830
<b>Log Splitters</b>			
200 Series Drive .....	PT5300		6857
<b>Pressure Washers</b>			
A25 Drive; Ser. No. 26000 & After .....	PT5762		6838
A40 Drive; Ser. No. 26001 & After .....	TY7745		②6851
<b>Sprayer Equipment</b>			
5; 5A; 5B Gear Pump .....	M44178		6729
Piston Pump .....	M41335		6732
7 Pump .....	R1561R	7530	
<b>Sweepers</b>			
31S Belt .....	M45815		6827
<b>JOLLYHOE</b>			
<b>Compost Grinders</b>			
<b>Clipper</b>			
Belt; W/5 H.P. Eng. ....		2290	6829
Belt; W/8 H.P. Eng. ....		2310	6831
<b>K &amp; S</b>			
<b>Edgers</b>			
488; 562 Blade .....		2280	6828
Electric Blade .....		2340	6834
KS-07 Blade .....		2280	6828
KS17; KS19; KS71; KS72; KS75 Blade .....		2310	6831
KS122; KS122A; KS366 Blade .....		2340	6834
KS800; KS970; KS1500; KS1505; KS2001; KS2003; KS2005 Blade .....		2310	6831
<b>KEE</b>			
<b>Edgers</b>			
Edger - Trimmer Blade .....		1240	6724
ET101 Belt .....		3290	
SE101 Belt .....			6930
<b>KEES, F.D.</b>			
<b>Aerators</b>			
SA-68; SL-300; SL-300-5 Belt .....	VB62F	3390	6939

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>KEES, F.D. - Continued</b>			
<b>Edgers</b>			
93V Blade .....		2340	
<b>Power Rake/Overseeder</b>			
100528 Drive; W/36" Belt O.C. ....	103032		6936
Drive; W/39" Belt O.C. ....	VB62F		6939
<b>Contour G.P.M.</b>			
Blade .....			6826
FN-100 Belt .....	VB62F	3390	6939
FW-9 Drive .....			6933
<b>HM61 Moto-Rake; HM61B Moto-Rake</b>			
Belt .....	VB62F		6939
P-65 Clutch .....	60119	3440	6944
ST-200; ST-280 Belt .....	VB62F	3390	6939
<b>KEMP</b>			
<b>Shredders</b>			
K6GH Belt .....			6966
<b>KINCO</b>			
<b>Power Rake/Overseeder</b>			
<b>Contour G.P.M.</b>			
Blade .....		2260	6826
<b>KING O LAWN</b>			
<b>Edgers</b>			
20A; 204F; 206; 216; 216B; 217B; 231 Belt .....		2270	6827
235 Belt .....		2300	6830
236; 242; 246; 261; 286 Belt .....		2270	6827
<b>LAMBERT</b>			
<b>Power Rake/Overseeder</b>			
<b>1248; LT20</b>			
Belt .....			6826
<b>Sweepers</b>			
<b>SG-5311WB</b>			
Belt; W/27" Belt O.C. ....		2270	6827
Belt; W/29" Belt O.C. ....	11575	2290	6829
VMB-5530S Drive .....	91232		6828
<b>LAWN BOY</b>			
<b>Edgers</b>			
1010; 1011; 1012; 1013; 1014 Blade .....	603682	2240	6824
1015; 1016 Belt .....	607198	2400	6840
<b>Power Rake/Overseeder</b>			
544834 Belt .....	548996		6830
<b>LAWN CHIEF</b>			
<b>Edgers</b>			
TT15 Drive .....			6831

②Two Required





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>LAWN CHIEF - Continued</b>			
<b>Edgers - Continued</b>			
TT16LD Blade .....			6831
<b>LAWN KEEPER</b>			
<b>Edgers</b>			
SKU1220433 Blade; W/2 H.P. Eng. ....	2310		6831
<b>LESCO</b>			
<b>Renovators</b>			
20 Pump Drive; W/Honda 8 H.P. Eng. ....	021811		3VX250
<b>LINDIG</b>			
<b>Compost Grinders</b>			
C-20; C-40; C-50 Belt .....	VB103	2490	6849
CQ5 Belt .....			BX48
JR-B Belt; W/Electric Eng. .... Belt; W/Gas Eng. ....		2440 2450	6844 6845
L-75 Belt .....	VB73		5V1600
M-4 Belt; W/Electric Eng. .... Belt; W/Gas Eng.; W/45" Belt O.C. .... Belt; W/Gas Eng.; W/47" Belt O.C. ....	VB10 VB61 VB55	2460 2450 2470	6846 6845 6847
M-8 Belt; W/46" Belt O.C. .... Belt; W/Electric Eng.; W/49" Belt O.C. .... Belt; W/Gas Eng.; W/47" Belt O.C. ....	VB10 VB103 VB55	2460 2490 2470	6846 6849 6847
<b>LITTLE WONDER</b>			
<b>Edgers</b>			
5001; 6001; 6031 Belt .....	177	2300	6830
6032; 6033 Drive .....	177	2300	
<b>MASSEY FERGUSON</b>			
<b>Edgers</b>			
3 H.P. Belt .....			6831
<b>P.T.O. Kits</b>			
Front Mounted P.T.O. Belt .....	513790M1		3V900
<b>MAXIM</b>			
<b>Edgers</b>			
ME3B Blade .....	272216		6831
ME3BW Blade .....	272240		6832
ME30B Blade; W/31" Belt O.C. .... Blade; W/32" Belt O.C. ....	272229 272240		6831 6832
<b>Garden Plows</b>			
PH50B Plow Hoss Drive .....	320272212		6864

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MCLANE</b>			
<b>Edgers</b>			
2 H.P. B. & S. Eng.; 2.2 H.P. Honda Eng.; 3 H.P. B. & S. Eng. Blade .....		2300	6830
100 Series; 800 Series Belt .....		2300	6830
<b>MERRY TILLER</b>			
<b>Edgers</b>			
150; 250 Belt .....	48350		6835
<b>MIGHTY MAC</b>			
<b>Shredders</b>			
5P Drive .....	0300001		6838
9P; 9PT Belt; W/5 H.P. Eng. ....	0300038		6855
12P; 12PT Belt; W/5 H.P. Eng. .... Belt; W/7 H.P. Eng. ....	0300038 0300113		6855 6853
<b>MONO</b>			
<b>Edgers</b>			
ET-2-BR Belt .....	ET127	2290	6829
MD5 Belt .....			6967
Rocket Belt .....			6829
<b>MONTGOMERY WARD</b>			
<b>Aerators</b>			
1426 Drive .....	308458	3360	6936
<b>Air Compressors</b>			
GIL2335A; GIL2337A Belt .....	1434		6728
GIL2338A Belt .....	1409	3520	6952
GIL2339A Belt .....	1434		6728
GIL21325A; GIL21326A Belt; W/47" Belt O.C. .... Drive .....	17653 14843		6847 6829
<b>Edgers</b>			
134A; 135; 136A; 137; 147A Drive .....	E027	2270	6827
596; 604 Blade .....	7540142		6673BR
4955 Belt .....	503849	2490	6849
37700 Drive .....	E027	2270	6827
CP134A; CP134B; CP136A; CP136B; CP137A; CP137B; CP144A; CP145A; CP37700 Belt .....	E027	2270	6827
TMO24596B Blade .....			6731
TMO24603; TMO24620; TMO24620A; TMO37654B; TMO37654E; TMO37659A Belt .....	7540142		6673BR
TMO248596 Blade .....			6731

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>Edgers - Continued</b>			
ZMY140A; ZMY140B; ZMY161A Belt .....	Y22	2300	6830
<b>Log Splitters</b>			
24435; 24435A Belt .....	7540278	2300	6830
24439A Forward .....	7540235		6835
Reverse .....	7540244		6840
24635B Belt .....	7540278	2300	6830
<b>Sweepers</b>			
294 Belt .....	L5055	1220	6722
5730 Belt .....	L5399	1210	6721
8469 Belt .....		1220	6722
<b>Vacuums</b>			
297A Traction .....	165110	1170	6717
675; 685; 689 Traction .....	7540219		6826
8250-2 Drive .....			6833
24677; 24678 Traction .....	7540219		6826
TMO37901A; TMO37906A; TMO37907A Drive .....	7540176	0230	
ZYJ297A; ZYJ297B Drive .....			6833
Speed Reducer .....	165110	1170	6717
<b>MTD PRODUCTS, INC.</b>			
<b>Aerators</b>			
DA528 Belt .....		3360	6936
<b>Edgers</b>			
3Z030 Belt .....		2230	6823
3Z230 Belt .....		2260	6826
3Z478 Belt .....	7540242	2320	6832
240-600; 240-600A; 240-602A; 241-595; 241-600; 242-595; 242-600; 243-540; 243-595; 243-596 Blade .....	7540142		6673BR
243-600; 243-603; 244-595; 244-600; 244-600A; 244-603; 245-596; 245-596C; 245-600; 245-600A Blade .....	7540142		6673BR
245-604 Blade .....	7540142		6673BR
245-675; 245-689 Drive .....	7540219	2260	6826
246-596; 246-600; 246-600A; 246-604 Blade .....	7540142		6673BR
246-675; 246-685; 246-689 Drive .....	7540219	2260	6826

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>Edgers - Continued</b>			
247-590; 247-590A; 247-596; 247-600; 247-600A; 247-604 Blade .....	7540142		6673BR
247-675; 247-685; 247-689 Drive .....	7540219	2260	6826
248-596; 248-600; 248-600A; 248-604; 249-600; 249-600A; 249-602; 249-602A; 249-604 Blade .....	7540142		6673BR
251-534; 251-536; 251-537 Drive .....	7540935		6831
251-586 Blade .....	7540142		6673BR
Blower .....	7540282		6372
Eng. ....	7540256		6729
252-534; 252-536 Drive .....	7540935		6831
252-586 Drive .....	7540142		6673BR
253-536 Drive .....	7540935		6831
253-586 Drive .....	7540142		6673BR
254-546; 254-556; 254-586; 254-588; 254-596; 254-598 Blade .....	7540142		6673BR
255-546; 255-588; 256-546; 256-588 Drive .....	7540142		6673BR
540-600 Blade .....	7540142		6673BR
<b>Edgers/Trimmers</b>			
25A; 520; 550; 551; 552; 554 Spindle .....	75404032		6619BR
<b>Front Mount Kits</b>			
190-943A; 197-943A; 199-941A; 199-942A Belt .....	7540218		6959
242-634 Front Wheel Drive .....	7540235		6835
Reverse .....	7540244		6840
19941-9; 19942-9; 19943-7 Belt .....	7540218		6959
<b>Front P.T.O. Kits</b>			
190-952; 194-952; 195-952; 198-952A; 199-952 Belt .....	7540229		6852
<b>Log Splitters</b>			
242-635; 243-635; 244-635 Forward .....	7540235		6835
Reverse .....	7540244		6840
244-638 Belt .....	7540278	2300	6830
245-635 Forward .....	7540235		6835
Reverse .....	7540244		6840
245-638 Belt .....	7540278	2300	6830
246-634 Belt .....	7540287	2290	6829
246-638; 247-638 Belt .....	7540278	2300	6830



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>				<b>PARKER</b>			
<b>Vacuums</b>				<b>Blowers</b>			
240-680A; 241-680A	Belt ..... 7540176	0230		Hurricane HC7080	Belt; W/8 H.P. Eng. .... 6996A		6738
242-675; 242-685; 242-689; 243-675; 243-685; 243-689	Drive ..... 7540219		6826	Hurricane HC7760	Belt; W/6 H.P. Eng. .... 73417A		6721
244-670A	Belt ..... 7540176	0230		Hurricane HC7880; Hurricane HC7980; Hurricane HC8380	Belt; W/8 H.P. Eng. .... 73417A		6721
244-675; 244-685; 244-687; 244-689	Drive ..... 7540219		6826	Hurricane HC17080	Belt; W/8 H.P. Eng. .... 6996A		6738
245-685	Belt ..... 7540219		6826	Hurricane HI8380; Hurricane HT8380	Belt; W/6 H.P. Eng. .... 73417A		6721
	Drive ..... 7540219	2260	6826	<b>Power Rake/Overseeder</b>			
246-670; 246-680; 247-680A	Belt ..... 7540176	0230		PR6719	Belt; W/33" Belt O.C.; W/5 H.P. Eng. .... 66100A		AX31
248-675	Drive ..... 7540219		6826		Belt; W/35" Belt O.C.; W/5 H.P. Eng. .... 66259A		6835
248-680A	Belt ..... 7540176	0230		PR7119F; PR7119K	Belt; W/B. & S. 5 H.P. Eng. .... 7701A		③6837
248-685; 248-689	Drive ..... 7540219		6826	PR7119T	Belt; W/5 H.P. Eng. .... 7070A		③6839
<b>NATIONAL MOWER</b>				PR8319	Belt; W/3.5 H.P. Eng. ....		6837
<b>Power Rake/Overseeder</b>				PR8319F; PR8319K	Belt; W/5 H.P. Eng. .... 7701A		③6837
Roto-Raker	Belt ..... 6939			PR8319T	Belt; W/5 H.P. Eng. .... 7761A		6838
<b>NEW IDEA</b>				PR8815-I/C	Belt ..... 7701A		③6837
<b>Sweepers</b>				PR8819-I/C-F-K	Belt ..... 88185A		6836
Electric	Belt ..... 120994		6820	PR8819-I/C-T	Belt ..... 7701A		③6837
<b>NOMA</b>				PR8919F	Belt ..... 89134A		6839
<b>Edgers/Trimmers</b>				PR8919T	Belt ..... 7701A		③6837
3710; 3711-0200	Drive ..... 32668		6833	PR26719	Belt; W/33" Belt O.C.; W/5 H.P. Eng. .... 66100A		AX31
5399-0100; 5399-0200; 5399-0300; 5399-0400	Drive ..... 2543		6828		Belt; W/35" Belt O.C.; W/5 H.P. Eng. .... 66259A		6835
85637; 85647; 85667	Blade ..... 88690		6833	PRO319	Belt ..... 7761A		6838
A2009-000	Blade; W/2 H.P. Eng. ....	2328		<b>Sweepers</b>			
A3009-000; A3009-010	Blade; W/3 H.P. Eng. ....	2328		Homemaster HM5728A	Belt; W/3 H.P. Eng. .... 47287A2	2250	6825
C3009-000	Drive ..... 32668		6833	Parkmaster PM36	Belt; W/3 H.P. Eng. .... 47287A1	2250	6825
EX3900	Blade ..... 32668		6833	Power Chief PC7525	Belt; W/3 H.P. Eng. .... 7549A	1400	6740
<b>OKLAHOMA TIRE &amp; SUPPLY</b>				Power Sweep PS2560	Belt; W/3 H.P. Eng. .... 6056A	2220	6822
<b>Edgers</b>				Power Sweep PS6025; Power Sweep PS7430	Belt; W/B. & S. 3 H.P. Eng. .... 6056A	2220	6822
240-600; 241-600; 242-600; 243-600; 244-600A; 245-600; 246-604; 249-600	Belt ..... 7540142		6673BR	Power Sweep PS7625	Belt; W/3 H.P. Eng. .... 7549A	1400	6740
<b>PANZER</b>				Power Sweep PS7730	Belt; W/3 H.P. Eng. .... 76432A	1310	6731
<b>P.T.O. Kits</b>				Power Sweep PS7930	Belt; W/3 H.P. Eng. .... 76433A	1230	6723
51PT	Belt ..... 51PT4	3350	6935	Power Sweep PS8230	Belt; W/23" Belt O.C.; W/3 H.P. Eng. .... 76433A	1230	6723
52PT; 53PT; 54PT; 55PT	Belt ..... 74223	3330	6933		Belt; W/31" Belt O.C.; W/3 H.P. Eng. .... 76432A	1310	6731

③Three Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PARKER - Continued</b>			
<b>Sweepers - Continued</b>			
<b>Power Sweep PS8930</b>			
Belt; W/24" Belt O.C.; W/3 H.P. Eng. ....	8989A	1240	6724
Belt; W/30" Belt O.C.; W/3 H.P. Eng. ....	8990A	1300	6730
<b>Vacuums</b>			
<b>Power Vac PV6806</b>			
Belt; W/29" Belt O.C.; W/6.25 H.P. Eng. ....	68355A		6829
Belt; W/30" Belt O.C.; W/6.25 H.P. Eng. ....	68358A		6830
Belt; W/38" Belt O.C.; W/6.25 H.P. Eng. ....	6996A		6738
<b>Power Vac PV6806SP-LP</b>			
Belt; W/6.25 H.P. Eng. ....	73239A		6830
<b>Power Vac PV7506; Power Vac PV7706; Power Vac PV7808</b>			
Belt; W/6, 8 H.P. Eng. ....	73417A		6721
<b>Power Vac PV8308</b>			
Belt; W/8 H.P. Eng. ....	73417A		6721
<b>Scavenger SV8230</b>			
Belt; W/B. & S. 5 H.P. Eng. ....	8614A		6744
Belt; W/Tecumseh 5 H.P. Eng. ....	8253A		6743
<b>Scavenger SV8330</b>			
Belt; W/Tecumseh 5 H.P. Eng. ....	8253A		6743
<b>Scavenger SV8630</b>			
Belt; W/5 H.P. Eng. ....	8614A		6744
<b>Scavenger SV8630-I/C-SP</b>			
Belt; W/3.5 H.P. Eng. ....	8685A		3VX670
<b>PARKTON</b>			
<b>Edgers</b>			
<b>SA-2172</b>			
Belt .....	PAS21	2340	6834
<b>PEMCO INTERNATIONAL</b>			
<b>Edgers</b>			
<b>Lil Tiger 51; Lil Tiger 57; Lil Tiger 60</b>			
Blade .....		2290	6829
<b>PENNEYS</b>			
<b>Edgers</b>			
<b>1708</b>			
Belt .....	311708	2280	6828
<b>1727; 1737</b>			
Belt .....	241750	2310	6831
<b>1739</b>			
Belt .....	241749	2410	6841
<b>1740; 1746</b>			
Belt .....	241750	2310	6831
<b>1749</b>			
Belt .....	241749	2410	6841
<b>1750</b>			
Belt .....	241750	2310	6831
<b>1757; 1758; 1759</b>			
Belt .....	311708	2280	6828
<b>Log Splitters</b>			
<b>246-638</b>			
Belt .....	7540278	2300	6830
<b>6036</b>			
Belt; W/35" Belt O.C. ....	7540235		6835
Belt; W/40" Belt O.C. ....	7540244		6840
<b>PLOW HOSS</b>			
<b>Garden Plows</b>			
<b>PH50B</b>			
Eng. To J.S. ....			6884

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>POWER TRIM</b>			
<b>Edgers</b>			
<b>100</b>			
Belt .....	134	2280	6828
<b>150</b>			
Belt .....	134	2280	6828
Blade .....	339	2280	6828
<b>200; 200H; 208H; 300</b>			
Blade .....	339	2280	6828
<b>300H</b>			
Blade .....	3391		AX26
<b>300IC; 308</b>			
Blade .....	339	2280	6828
<b>308H</b>			
Blade .....	3391		AX26
<b>308IC</b>			
Blade .....	339	2280	6828
<b>500</b>			
Belt .....	134	2280	6828
<b>800</b>			
Belt .....	238	2290	6829
<b>Apache 100; Apache 200; Apache 600; Apache 1500</b>			
Belt .....	237	2280	6828
<b>Senior; Std.</b>			
Belt .....	530	2280	6828
<b>PRAXIS</b>			
<b>Stump Grinders</b>			
<b>Stump Machine</b>			
Blade .....			26957
<b>PRO CHIP</b>			
<b>Chippers</b>			
<b>18"</b>			
P.T.O. ....			3VX400
Powerfeed .....			AX35
<b>24"</b>			
P.T.O. ....			3VX400
Powerfeed .....			AX36
<b>PROFESSIONAL HARDWARE</b>			
<b>Edgers</b>			
<b>8244-0; 8244-1; 8244-2; 8244-3</b>			
Belt .....	7540142		6673BR
<b>PROMARK</b>			
<b>Shredders</b>			
<b>410</b>			
Fan & Alt .....		7435	
Gov. ....		7550	
<b>ROOF</b>			
<b>Weed Cutters</b>			
<b>400; 4006</b>			
Blade; W/45" Belt O.C. ....	452		6945
Blade; W/62" Belt O.C. ....	430		6962
Traction .....	431		6834
<b>Piranha</b>			
Blade .....	B50		6953
<b>Ranger Pro; SP82450; SP82670; VP24</b>			
Blade .....	430		6962
Traction .....	431		6834
<b>VP65; VP75</b>			
Belt .....	428	3720	6972

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROOF - Continued</b>			
<b>Weed Cutters - Continued</b>			
<b>Weed Weevil</b>			
Blade .....	430		6962
Traction .....	431		6834
<b>ROTA-TRIM</b>			
<b>Edgers</b>			
<b>2G62C; 2G62GT</b>			
Belt .....		2270	6827
<b>2G77D</b>			
Belt .....		2320	6832
<b>2G77DW</b>			
Belt .....		2340	6834
<b>2G77E</b>			
Belt .....		2320	6832
<b>2G77EW</b>			
Belt .....		2340	6834
<b>2G77S</b>			
Belt .....		2320	6832
<b>2G77SW</b>			
Belt .....		2340	6834
<b>ROTO-HOE</b>			
<b>Compost Grinders</b>			
<b>500-H; 500-T; 550-H</b>			
Belt .....	101	2590	6859
<b>2000H</b>			
Belt; W/B. & S. 8 H.P. Eng. ....	804		6860
Belt; W/Kohler 8 H.P. Eng. ....	908		6861
<b>2011</b>			
Belt; W/3" Chipper .....	1542D		6959
<b>SK-5 Chipper</b>			
Belt .....	7569		6827
<b>Shredders</b>			
<b>500H; 500HCP</b>			
Belt; W/3" Chipper .....	101A		6858
<b>500T</b>			
Belt .....	101	2510	6851
<b>501H; 501T</b>			
Belt .....	102		6861
<b>509H; 509T</b>			
Drive .....	108	2610	6861
<b>550H</b>			
Belt .....	101	2510	6851
<b>551H</b>			
Belt .....	102		6861
<b>800HCP</b>			
Flywheel; W/3" Chipper .....	A53		6855
Hammermill; W/3" Chipper .....	101A		6858
<b>2011HCP</b>			
Flywheel; W/3" Chipper .....	1542E		6957
Hammermill; W/3" Chipper .....	1542C		6960
<b>Sprayer Equipment</b>			
<b>TAS-25; TAS-55</b>			
Pump .....	2300	2300	6830
<b>ROTO-RAKER</b>			
<b>Power Rake/Overseeder</b>			
<b>Deluxe</b>			
Belt .....			6838
<b>FW37</b>			
Belt .....		3390	6939

②Two Required ③Three Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROYAL MOWER &amp; EDGER</b>			
<b>Edgers</b>			
<b>Heavy Duty</b>			
Belt; W/18" Belt O.C. ....		2180	6818
Belt; W/36" Belt O.C. ....		2360	6836
Belt; W/40" Belt O.C. ....		2400	6840
<b>Junior; Little Queen</b>			
Belt .....		2340	6834
<b>RUHMANN</b>			
<b>Edgers</b>			
<b>FB-16 Jet-Line Marker</b>			
Belt .....	7J	2300	6830
<b>R-22-C; R-22-CP; R-22-CW</b>			
Belt .....	11	2300	6830
<b>R-34-CW</b>			
Belt .....	27	2260	6826
<b>R-42-C; R-42-CW; R-42-P</b>			
Belt .....	2380549	2350	6835
<b>R-61-CW</b>			
Belt; W/26" Belt O.C. ....	2380550	2260	6826
Belt; W/35" Belt O.C. ....	17	2350	6835
<b>R-64</b>			
Belt .....	2380549	2350	6835
<b>RS-43-C</b>			
Belt; W/26" Belt O.C. ....	2380550	2260	6826
Belt; W/35" Belt O.C. ....	17	2350	6835
<b>RYAN</b>			
<b>Aerators</b>			
<b>A3</b>			
Belt; W/30" Belt O.C. ....	548404	2300	6830
Belt; W/46" Belt O.C. ....	GA1064	3460	6946
<b>Core Processor</b>			
Belt .....	548968		6224
<b>E</b>			
Belt; W/30" Belt O.C. ....	548404	2300	6830
Belt; W/46" Belt O.C. ....	GA1064	3460	6946
<b>Greensaire 1</b>			
Belt .....	548428	3410	6941
<b>Greensaire 2</b>			
Belt .....	549248		6838
<b>Greensaire 16</b>			
Belt .....			②6844
<b>Lawnaire; Lawnaire II</b>			
Belt .....	548423		6933
<b>Lawnaire IV; Lawnaire V Plus</b>			
Drive; W/47" Belt O.C. ....	521613		6847
Drive; W/48" Belt O.C. ....	4114319		6658BR
<b>M18-1; M22-1</b>			
Belt .....	135M182	3340	6934
<b>Motoraire</b>			
Belt .....	M60	3390	6939
<b>Edgers</b>			
<b>Pro Edge</b>			
Belt .....	548819		3V355
<b>Power Rake/Overseeder</b>			
<b>Lawnboy</b>			
Belt .....	548996		6830
<b>Mataway</b>			
Belt .....	548606		③3V400
Front Wheel Drive .....	548403		6828
<b>Ren-O-Thin II</b>			
Belt .....	R119		6929

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>RYAN - Continued</b>			
<b>Power Rake/Overseeder - Continued</b>			
Ren-O-Thin III Belt .....	548996		6830
Ren-O-Thin IV Belt .....	545200		6830
<b>Sod Cutters</b>			
CDV218 Drive .....			6964
JR12; JR18 Belt .....	548421		6864
R18-1; R18-2; R18-3 Belt .....	548404	2300	6830
<b>Spreaders</b>			
<b>Spread-Rite</b>			
Conveyor .....	548403		6828
Drive; W/31" Belt O.C. ....	548405		6831
Drive; W/39" Belt O.C. ....	548413		6839
Front Wheel Drive .....	548408		6833
<b>Turf Rollers</b>			
<b>Rollaie 544839</b>			
Forward .....	521142		6833
Reverse .....	521143		6372
Rollaie R22-1 Belt .....	548424	3340	6934
<b>S &amp; H MANUFACTURING</b>			
<b>Edgers</b>			
<b>Commercial 3 To 5 H.P.</b>			
Belt .....	120B	2500	6850
<b>Curb Rider 3 To 5 H.P.</b>			
Belt .....	303	2350	6835
<b>SALSCO</b>			
<b>Aerators</b>			
<b>30-6; 30-6S; 30-12; C-1C</b>			
Belt .....	B070		②6861
<b>FTA60-24</b>			
Belt .....			②6953
<b>SANBORN MANUFACTURING CO.</b>			
<b>Air Compressors</b>			
<b>8G-23, 8GE-23</b>			
Belt; W/8 H.P. Eng. ....	0070028		6864
<b>11GE-22</b>			
Belt .....	0070003		6867
<b>19M33-2</b>			
Belt; W/1/3 H.P. Electric Eng. ....	0070009	2450	6845
<b>31-15</b>			
Belt; W/3 H.P. Eng.; W/58" Belt O.C. ....	0070025	2580	6858
Belt; W/3 H.P. Eng.; W/65" Belt O.C. ....	0070001		6865
<b>33-20</b>			
Belt; W/3 H.P. Eng. ....	0070001		6865
<b>34A50 Series; 34B50 Series</b>			
Belt; W/1/2 H.P. Electric Eng. ....	0070010	2460	6846
<b>44A100 Series; 44B100 Series</b>			
Belt; W/1 H.P. Electric Eng.; W/44" Belt O.C. ....	0070022	2440	6844
Belt; W/1 H.P. Electric Eng.; W/47" Belt O.C. ....	0070011	2470	6847
<b>44GU3 Series</b>			
Belt; W/3 H.P. Gas Eng. ....	0070022	2440	6844
<b>51-17</b>			
Belt; W/5 H.P. Eng. ....	0070001		6865

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SANBORN MANUFACTURING CO. - Continued</b>			
<b>Air Compressors - Continued</b>			
<b>51-22; 53-22</b>			
Belt; W/5 H.P. Eng. ....	0070004		6868
<b>53-23</b>			
Belt; W/5 H.P. Eng. ....	0070001		6865
<b>64A100 Series</b>			
Belt; W/1 1/2 H.P. Electric Eng.; W/47" Belt O.C. ....	0070011	2470	6847
Belt; W/1 1/2 H.P. Electric Eng.; W/48" Belt O.C. ....	0070020	2480	6848
<b>64A150 Series</b>			
Belt; W/1 1/2 H.P. Electric Eng. ....	0070020	2490	6849
<b>64B100 Series</b>			
Belt; W/1 1/2 H.P. Electric Eng.; W/47" Belt O.C. ....	0070011	2470	6847
Belt; W/1 1/2 H.P. Electric Eng.; W/48" Belt O.C. ....	0070020	2480	6848
<b>64B150 Series</b>			
Belt; W/1 1/2 H.P. Electric Eng. ....	0070020	2490	6849
<b>64BGU5</b>			
Belt; W/5 H.P. Gas Eng. ....	0070011	2470	6847
<b>71-32; 73-32</b>			
Belt; W/7 1/2 H.P. Eng. ....	0080012		6985
<b>84A100 Series</b>			
Belt; W/1 1/2 H.P. Electric Eng.; W/47" Belt O.C. ....	0070011	2470	6847
Belt; W/1 1/2 H.P. Electric Eng.; W/48" Belt O.C. ....	0070020	2480	6848
<b>84A150 Series</b>			
Belt; W/1 1/2 H.P. Electric Eng. ....	0070020	2490	6849
<b>84GU3 Series</b>			
Belt; W/3 H.P. Gas Eng. ....	0070020	2480	6848
<b>84TE15; 84TE20</b>			
Belt; W/1, 1 1/2 H.P. Electric Eng. ....	0080003	3500	6950
<b>101-38; 103-38</b>			
Belt; W/10 H.P. Eng. ....	0080012		6985
<b>104A200 Series</b>			
Belt; W/2 H.P. Electric Eng.; W/48" Belt O.C. ....	0070020	2480	6848
Belt; W/2 H.P. Electric Eng.; W/49" Belt O.C. ....	0070012	2490	6849
<b>104B150 Series</b>			
Belt; W/1 1/2 H.P. Electric Eng. ....	0070020	2490	6849
<b>104B200 Series</b>			
Belt; W/2 H.P. Electric Eng.; W/48" Belt O.C. ....	0070020	2480	6848
Belt; W/2 H.P. Electric Eng.; W/53" Belt O.C. ....	0070037	2530	6853
<b>104B250U</b>			
Belt; W/2 1/2 H.P. Electric Eng. ....	0070037	2530	6853
<b>104BGU5</b>			
Belt; W/5 H.P. Gas Eng. ....	0070012	2490	6949
<b>109B300</b>			
Belt; W/2 1/2 H.P. Electric Eng. ....	0070037	2530	6853
<b>112A300 Series</b>			
Belt; W/3 H.P. Electric Eng. ....	0080023	3480	6948
<b>112B300</b>			
Belt; W/3 H.P. Electric Eng. ....	0070012	2490	6949
<b>112B300 Series</b>			
Belt; W/3 H.P. Electric Eng. ....	0070038	2550	6855
<b>143BGU5</b>			
Belt; W/5 H.P. Gas Eng. ....	0080022	3490	6949
<b>143GU5 Series; 143TG50</b>			
Belt; W/5 H.P. Gas Eng. ....	0080003	3500	6950

②Two Required





Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.		
<b>SANBORN MANUFACTURING CO. - Continued</b>				<b>SEARS ROEBUCK</b>					
<b>Air Compressors - Continued</b>				<b>Edgers</b>					
<b>153-60</b> Belt; W/15 H.P. Eng. ....	0070029		6872	<b>536.79632</b> Drive .....	32668		6833		
<b>165TG50</b> Belt; W/5 H.P. Gas Eng. ....	0080022	3490	6949	<b>536.85590</b> Drive .....	2543		6828		
<b>203-88</b> Belt; W/20 H.P. Eng. ....	0070059		6882	<b>536.85601</b> Drive .....	22224	2320			
<b>253-98</b> Belt; W/25 H.P. Eng. ....	0070032		68107	<b>536.85605</b> Drive .....	32668		6833		
<b>400A Series; 400A60H Series; 400A60V Series</b> Belt; W/4 H.P. Electric Eng. ....	0080022	3490	6949	<b>536.85610; 536.85612</b> Drive .....	22224	2320			
<b>400B Series</b> Belt; W/4 H.P. Electric Eng. ....	0080036	3540	6954	<b>536.85615</b> Drive .....	39159		6828		
<b>500A Series</b> Belt; W/4 H.P. Electric Eng. ....	0080022	3490	6949	<b>536.85620; 536.85621; 536.85623; 536.85624;</b> <b>536.85625; 536.85626; 536.85627; 536.85628</b> Drive .....	2543		6828		
<b>500B Series</b> Belt; W/5 H.P. Electric Eng. ....	0080036	3540	6954	<b>536.85630; 536.85631; 536.85632; 536.85634;</b> <b>536.85635; 536.85636</b> Drive .....	22224	2320			
<b>500B60V Series</b> Belt .....	0080036	3540	6954	<b>536.85637; 536.85638; 536.85639</b> Drive .....	32668		6833		
<b>V89A200 Series; V89B200</b> Belt; W/1 1/2 H.P. Electric Eng. ....	0070020	2490	6849	<b>536.85640; 536.85641; 536.85642; 536.85643;</b> <b>536.85645</b> Drive .....	22224	2320			
<b>SARLO</b>				<b>536.85647; 536.85648; 536.85649</b> Drive .....				32668	6833
<b>Edgers</b>				<b>536.85650; 536.85660; 536.85662; 536.85663;</b> <b>536.85664</b> Drive .....				22224	2320
<b>125</b> Blade .....	5585	3560		<b>536.85667; 536.85668; 536.85669; 536.85670</b> Drive .....	32668		6833		
<b>SCAG POWER EQUIPMENT, INC.</b>				<b>536.85671</b> Drive .....					6833
<b>Edgers</b>				<b>536.85680</b> Drive .....				32668	6833
<b>Edger</b> Drive .....	48452		6830	<b>536.85681</b> Drive .....			6833		
<b>Grass Catchers</b>				<b>536.85690</b> Drive .....				32668	6833
<b>GC-SSZ42; GC-SSZ48</b> Drive .....	48913		6831	<b>536.85691</b> Drive .....			6833		
<b>GC-STC48; GC-STC52</b> Blower; Ser. No. 9490001 Thru 9499999 ...	482278		6869	<b>536.85770; 536.85773; 536.85775; 536.85776;</b> <b>536.85778; 536.85810; 536.85811; 536.85812;</b> <b>536.85813; 536.85814</b> Drive .....	2543		6828		
Blower; Ser. No. B8200001 Thru B9199999	482379		6873	<b>536.85816; 536.85817</b> Drive .....	2543		6828		
<b>GC-STC61</b> Blower .....	482379		6873	<b>536.85818; 536.85819</b> Drive .....	22224	2320			
<b>GC-STC-CS48; GC-STC-CS52</b> Blower; Ser. No. 9490001 Thru 9499999 ...	482278		6869	<b>536.87000; 536.87001; 536.87010; 536.87020;</b> <b>536.87030; 536.87040; 536.87041; 536.87042;</b> <b>536.87043; 536.87045</b> Drive .....	32668		6833		
Blower; Ser. No. B8200001 Thru B9199999	482379		6873	<b>536.87050; 536.87051; 536.87052; 536.87053;</b> <b>536.87054; 536.87060; 536.87080; 536.87090;</b> <b>536.87091; 536.87092</b> Drive .....	32668		6833		
<b>GC-STT61</b> Blower; Ser. No. 9017 & After .....	482379		6873	<b>536.87451; 536.87452</b> Drive .....			6833		
Blower; Ser. No. E0700001 Thru E0799999	482379		6873	<b>536.376514; 536.376516; 536.376525;</b> <b>536.376526; 536.376537</b> Drive .....	32668		6833		
<b>GC-STT-CS61</b> Blower; Ser. No. 9017 & After .....	482379		6873						
Blower; Ser. No. E1200001 Thru E1299999	482379		6873						
<b>GC-STWC61; GC-STWC-CS61</b> Blower; Ser. No. 9500001 Thru 9559999 ...	482379		6873						
Blower; Ser. No. A9200001 Thru A9499999	482379		6873						
Blower; Ser. No. E0100001 Thru E0399999	482379		6873						
<b>SCHWEISS</b>									
<b>Grass Catchers</b>									
<b>Grass Catcher</b> Belt; W/Diesel Eng. ....	230010		6975						
Belt; W/Man. Clutch .....	230018		6974						

Lawn & Garden Equipment



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>Edgers - Continued</b>			
536.772100; 536.772101; 536.772200 Blade .....	32668		6833
536.772210 Blade .....	32668	2328	
536.772301 Blade .....	32668		6833
536.772321; 536.772340; 536.772341 Blade .....	32668	2328	
536.772400; 536.787541; 536.787581 Blade .....	32668		6833
536.796510; 536.796511; 536.796512; 536.796513 Drive .....	32668		6833
536.796514 Blade .....	32668		6833
536.796515 Drive .....	32668		6833
536.796516 Blade .....	32668		6833
536.796520 Blade .....	32668	2328	
536.796521; 536.796523; 536.796525 Blade .....	32668		6833
536.796526 Blade .....	32668	2328	
536.796530; 536.796531; 536.796532; 536.796536 Drive .....	32668		6833
536.797400; 536.797460; 536.797470; 536.797481 Blade .....	32668		6833
536.797510 Blade .....	88690		6833
536.797511; 536.797512; 536.797513 Blade .....	32668		6833
536.797520 Drive .....	8869		6833
536.797521 Blade .....	32668		6833
536.797530 Drive .....	8869		6833
536.797531 Blade .....	32668		6833
536.797532 Drive .....	8869		6833
536.797540; 536.797541 Blade .....	32668		6833
536.797560 Blade .....	88690		6833
536.797570; 536.797572; 536.797581; 536.797590; 536.797591 Blade .....	32668		6833
536.857300 Drive .....	502136		6831
536.870451; 536.870452; 536.870453; 536.870541; 536.870542; 536.870601; 536.870602; 536.870603; 536.871000; 536.871001 Drive .....	32668		6833

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>Edgers - Continued</b>			
536.871002; 536.871003; 536.871004; 536.871100; 536.871101; 536.871200; 536.871300; 536.871301; 536.871302; 536.8711012 Drive .....	32668		6833
663.875300 Blade .....			6728
79654 Blade .....	2058	2300	
<b>Edgers/Trimmers</b>			
536.772300 Blade .....	88690		6833
536.772320 Blade .....	32668	2328	
536.796537; 536.797480; 536.797561; 536.797580 Blade .....	32668		6833
917.773704; 917.773705; 917.773706; 917.773754 Drive .....	185476		6743
<b>Sprayer Equipment</b>			
131.446224 Drive .....	STD304270	2270	6827
131.447120; 131.447240 Drive .....			6828
147.446224 Drive .....			6827
147.447120; 147.447240 Drive .....			6828
147.447360 Drive .....			6831
471.446210; 471.446211; 471.446220 Drive .....		2270	6827
471.446223 Pump .....		2270	6827
471.446260 Drive .....		2270	6827
471.446261 Pump .....	304280	2280	6828
471.446262 Pump .....	STD304280	2280	6828
471.446880 Pump .....	304280	2280	6828
471.446881 Pump .....	STD304280	2280	6828
471.446890 Drive .....		2270	6827
471.461211 Pump .....	STD303310		6731
471.461212 Pump .....	STD304310	2310	6831
471.462821 Drive .....	303310	1310	6731
<b>Sweepers</b>			
536.79620 Drive .....	8597		6822
536.79621 Drive .....			6820
536.79623; 536.79970; 536.79971; 536.79972 Drive .....	8597		6822



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>Sweepers - Continued</b>			
536.79980 Drive .....	8597	2220	6822
536.79981; 536.79982; 536.79983; 536.79984; 536.79985 Drive .....	8597		6822
536.83850 Drive .....	LP2154	2200	6820
536.83890 Drive .....	RP8096	2260	6826
536.83990; 536.83991; 536.83992 Drive .....			6820
<b>Weed Cutters</b>			
536.773400 Drive .....	740259		6741
<b>SENSATION</b>			
<b>Edgers</b>			
50S1 (TG-42); 50S2 (TG-43) Drive .....	153501	2280	6828
<b>Power Rake/Overseeder</b>			
10A5 Belt .....	VB62F		6939
10P3A Belt; W/34" Belt O.C. .... Belt; W/36" Belt O.C. ....		3340 3360	6934 6936
10R5; 54400; 54401 Belt .....	VB62F		6939
<b>SHAW</b>			
<b>P.T.O. Kits</b>			
<b>Front Mounted</b>			
Drive .....	S4763		6935
<b>SIMPLICITY</b>			
<b>Chipper/Shredders</b>			
612 Rotor; Mfr. No. 1692204 .....	3080912		6928
912 Rotor; Mfr. No. 1692205, 1692206 .....	3080912		6928
1692204; 1692205; 1692206 Drive .....	3080912		6928
<b>Starter Kits</b>			
152 Starter .....	122039		6732
<b>SMITH CO.</b>			
<b>Sprayer Equipment</b>			
Spray Star 3000 W.P. & Alt. ....	JB325	7320	
<b>SNAPPER</b>			
<b>Aerators</b>			
PP5000 Power Plug Drive .....	76779		6839
<b>Edgers</b>			
ET200; ET200B; ET250-2; ET250T-2; ET300; ET300B; ET300C; ETC300B Drive .....	23226		6831
<b>Power Rake/Overseeder</b>			
3000 Drive .....	76145		6623BR
Powerrake Drive; W/5 H.P. Eng. ....	76085		6837

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>Power Rake/Overseeder - Continued</b>			
Powerrake II Drive; W/3 H.P. Eng. ....	77094		6829
<b>Power Slicers</b>			
5000 Drive .....	76085		6837
<b>STEINER TURF</b>			
<b>Edgers</b>			
DE160 Drive .....	81A88		6890
<b>SUNBEAM CORP.</b>			
<b>Edgers</b>			
919B Belt .....	32668		6833
<b>SWEEPSTER</b>			
<b>Brooms</b>			
C-36 Drive .....	06033		A38
Traction .....	06034	2380	6838
C-36BFS Drive .....	060263		6838
Traction .....	060165		A35
C-36RS Drive .....	060264		6840
Traction .....	060263		6838
C-36TW Belt .....			②6844
TR-48 Drive .....	060096		A51
Gutter Brush .....	060064	2760	6876
<b>TANAKA KOGYO (USA) CO. LTD.</b>			
<b>Generators</b>			
Reg 800; Reg 1000 Belt .....	02630452200		6834
<b>THESMAN INDUSTRIES</b>			
<b>Edgers</b>			
C-358XL; T-27; T-28; T-37; T-38 Belt .....			6834
TC-26 Belt .....	1111		6824
<b>TORO</b>			
<b>Aerators</b>			
88 Drive; W/B. & S. 3 H.P. Eng. ....	012640530		6952
09110; 09120 Drive - Coring Head .....	664070		6625BR
72110 Belt; For Model 270H Hydro. Tractor .....	926718		6463BR
<b>Blowers</b>			
67 Drive; W/3-Point Drive .....	012640030		3V335
<b>Chippers</b>			
8 Drive .....	012640220		6866
986 Pump Drive .....	012640120		3VX950
<b>Edgers</b>			
52432; 58410; 58430; 58431; 58432 Blade .....	520320	2295	

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>Seeders</b>			
84 J.S.; W/B. & S. 18 H.P. Eng. ....	012640110		3VX425
85 Drive; W/B. & S. 5 H.P. Eng. ....	012640360		3V335
<b>Vacuums</b>			
62911; 62912; 62922; 62923 Drive .....	205990		6750
<b>TRAC VAC</b>			
<b>Vacuums</b>			
854 Primary .....		2410	6841
Secondary .....		2270	6827
856 Belt .....		2290	6829
1080 Belt .....			②6837
<b>TRAIL MATE</b>			
<b>Edgers</b>			
EZ Edge Belt .....		1240	
N7502; N7503; N7505 Belt .....	E027	2270	6827
<b>TRIM-IT</b>			
<b>String Trimmer</b>			
TR-100 Clutch; W/4 H.P. Eng. ....	7530009		6856
<b>TROY BILT</b>			
<b>Shredders</b>			
5-8-2 G/C; 5-8-2 G/M Drive .....	18161410		6935
11427; 11428 Drive .....	W56290SPL		6929
Super Tomahawk I Drive .....	W5L350		6935
Super Tomahawk II Drive .....	W5L290		6929
Tomahawk 1 Drive .....	18161410		6935
Tomahawk 11 Drive .....	W56290SPL		6929
<b>Vacu-Cuts</b>			
PRO220 Blade .....	7524058		6846
PRO223 Blade .....	7524058		6846
Drive .....	7523058		6828
PROK243 Blade .....			6830
Drive .....	7523058		6828
<b>TRU-CUT</b>			
<b>Edgers</b>			
Electric Blade; W/2, 3.5 H.P. Eng. ....			6829
TC38L Blade .....			6828
TC370B Eng. To Blade .....	4L280	2280	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TRU-TEST</b>			
<b>Edgers</b>			
TT15; TT16LD Drive .....			6831
<b>TURFCO MFG., INC.</b>			
<b>Aerators</b>			
Sub Air Belt .....	650903		6957
<b>Pipe Layers</b>			
100A Arm Actuating Drive .....	650902		6955
140A Arm Actuating Drive .....	651172		②6963
180A Arm Actuating Drive .....	651387		②6971
Main Drive .....	655319		6841
Piper Belt .....			6966
<b>Sod Cutters</b>			
A Main Drive .....	655571		6844
K Arm Actuating Drive .....	651272		6840
Pro Sod Cutter Belt .....			6840
Prolite Belt .....	A36		6838
Slice-N-Rake Belt .....			6826
<b>Soil Processors</b>			
1823 Fan & Alt .....		7375	
<b>Spreaders</b>			
F-8A Conveyor & Brush Drive .....	650833		6951
Main Drive .....	650833		6951
F-15 Conveyor & Brush Drive .....	655865		6954
Main Drive .....	655865		6954
<b>TURF-MITE</b>			
<b>Trenching Saws</b>			
Ground Saw Blade .....			6829
<b>UNICO</b>			
<b>Edgers</b>			
6021; 6021-0; 6021-1; 6021-2; 6021-41; 6021-51; 6021-61; 6021-71; 6021-81 Blade .....	7540142		6673BR
<b>WEST POINT</b>			
<b>Aerators</b>			
AS-1; AS-2 Belt .....	9127	3500	6950
AS-12; AS-13 Belt .....	9382	3370	6937
EA Belt .....	9158	3330	6933
EA-2 Belt; W/33" Belt O.C. ....	9158	3330	6933
Belt; W/45" Belt O.C. ....	9283	3450	6945
EA-3 Belt .....	9081	3360	6936

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WEST POINT - Continued</b>			
<b>Aerators - Continued</b>			
GL			
Belt .....	9003		B51
GL-2			
Belt .....	9065	3460	6946
GL-3			
Belt; W/45" Belt O.C. ....	9283	3450	6945
Belt; W/46" Belt O.C. ....	9065	3460	6946
Belt; W/50" Belt O.C. ....	9127	3500	6950
JR-1; JR-1A			
Belt .....	9065	3460	6946
JR-2			
Belt .....	9811	3430	6943
MC-2			
Belt .....		3440	6944
<b>WESTERN AUTO</b>			
<b>Composters</b>			
4XF5850			
Drive .....	14843		6829
GIS233A			
Drive .....	1409	3520	6952
GIS7500A97			
Traction .....	18055	2300	
<b>Vacuums</b>			
95-5865-1; MTD5865A08			
Trans. ....	7540176	0230	
<b>WHEEL HORSE</b>			
<b>Edgers</b>			
6094			
Belt .....		2300	6830
<b>P.T.O. Kits</b>			
8-3211			
Belt .....	7776		6885
66			
Drive; W/37" Belt O.C. ....	1552	2370	6837
Drive; W/42" Belt O.C. ....	1550	2420	6842
<b>WHITE OUTDOOR PRODUCTS</b>			
<b>Edgers</b>			
244-595; 244-596; 244-604; 990-007; 991-007; 994-320			
Belt .....	7540142		6673BR
<b>Log Splitters</b>			
244-638			
Belt .....	7540278	2300	6830
994-291			
Belt; W/35" Belt O.C. ....	7540235		6835
Belt; W/40" Belt O.C. ....	7540244		6840
<b>Vacuums</b>			
675; 677; 685			
Drive .....	7540219		6826
<b>YARD MACHINES</b>			
<b>Edgers</b>			
25A201G			
Spindle .....	7540489		6744
25A510A			
Blade Drive .....	7540343		6731
25A532A			
Blade Drive .....	7540132		3V375

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>YARD MARVEL</b>			
<b>Aerators</b>			
YMPA Lawn Plugger			
Drive .....	PA2470		6847
<b>Power Rake/Overseeder</b>			
CGC			
Belt .....			6941
CMR; MR-5B			
Drive .....	MR77760		6937
<b>YARD VAC</b>			
<b>Edgers</b>			
PEB 390; Profile			
Belt .....		2240	6824
<b>Power Rake/Overseeder</b>			
TCB-5; TCH-5			
Belt .....			6828
<b>YARD-MAN</b>			
<b>Edgers</b>			
247-596			
Blade .....	7540142		6673BR
251-534			
Blade .....	7540935	2310	6831
251-586; 24520-9; 24596-1; 24597-1; 24598-1; 24604-8; 24620-1; 246046			
Blade .....	7540142		6673BR
<b>Front Mount Kits</b>			
Kits			
Drive .....	7540218		6959
<b>Log Splitters</b>			
24635			
Forward .....	7540235		6835
Reverse .....	7540244		6840
24638			
Hyd. ....	7540278	2300	6830
<b>P.T.O. Kits</b>			
19952			
P.T.O. ....	7540229		6852
<b>Vacuums</b>			
241-687			
Drive .....	7540219	2260	6826
24680-0; 24680-1; 24680-8; 24680-9			
Belt .....	7540176	0230	
24687			
Drive .....	7540219	2260	6826
<b>YAZOO</b>			
<b>Edgers</b>			
ET-100			
Drive .....	205144		6844
ET-200			
Drive .....	205030	2300	6830
ET-300			
Drive .....	205525	2350	6835
<b>YAZOO/KEES</b>			
<b>Power Rake/Overseeder</b>			
RBSIC050; RBSIT550; RHON050; SBSIC050			
Drive .....	100439	2370	

Lawn & Garden Equipment



Manufacturers' Part Number Shown for Reference Only

Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALDENS</b>			
<b>Mower Attachments</b>			
32" Belt .....	7540113	3480	6948
<b>Snow Thrower Attachments</b>			
Snow Thrower Belt .....	7540113	3480	6948
<b>ALLIS-CHALMERS</b>			
<b>Generator Attachments</b>			
Generators Belt .....	2025463		6835
<b>Grass Catcher Attachments</b>			
1691883 Drive .....	1711901		6835
<b>Mower Attachments</b>			
<b>48" Rotary – Compact Tractor</b>			
Clutch .....	1671076		6765BR
<b>60" Center Mtd – Compact Tractor</b>			
Drive .....	1664644		6378
1691147 Mower Drive .....	1665024		6854
1691148 Mower Drive .....	1713515		6458BR
1691220 Arbor .....	1656960		6811BR
P.T.O. ....	1666801		6640BR
1691221 Arbor .....	1657044		6521BR
P.T.O. ....	1713515		6458BR
1691260 Drive .....	1700415		6732
1691420 Arbor .....	1713549		6478BR
1691424 Arbor .....	1668066		6481BR
1691426 Arbor .....	1703466		6484BR
1691438 Mower Drive .....	1665024		6854
1691606 Drive .....	1679914		6749
1691607 Drive .....	1679913		6745
1691712 Arbor .....	1703466		6484BR
1691810 Drive .....	1700415		6732
1691815 Arbor .....	1716854		6643BR
1691816 Arbor .....	1721532		6798BR
P.T.O. ....	1601672		6799BR
1691878 Arbor .....	1712481		6860
Drive .....	1712482		6878
1691880 Arbor .....	1712937		AX110
Drive .....	1712595		BX108
1691881 Arbor .....	1712596		AX120

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>1691881 – Continued</b>			
Drive .....	1712595		BX108
1691992 Mower Drive .....	1665024		6854
1691998 Drive .....	1700415		6732
1692003 Drive .....	1679914		6749
1692030 Drive .....	1707956		6739
1692035 Arbor .....	1721532		6798BR
P.T.O. ....	1601672		6799BR
1692038 Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
1692172; 1692173 Drive .....	1719746		6873
1692174 Drive .....	1719819		6434BR
1692257 Drive .....	1679914		6749
1692410 Arbor .....	1713549		6478BR
1692544 Drive .....	1719746		6873
1692546 Drive .....	1719819		6434BR
1692589; 1692683 Arbor .....	1716854		6643BR
1692685; 1692687 Arbor .....	1721532		6798BR
P.T.O. ....	1601672		6799BR
1692689 Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
1692716 Drive .....	1707956		6739
1692858 Drive .....	1717146		6736
1692882 Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
1692913 Arbor .....	1719819		6434BR
1692915 Arbor .....	1713549		6478BR
1692936 Drive .....	1679914		6749
1693079 Arbor .....	1716854		6643BR
1693106 Drive .....	1717146		6736
1693228 Drive .....	1707956		6739
1693236 Arbor .....	1703836		6524BR
P.T.O. ....	1719746		6873





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ALLIS-CHALMERS - Continued</b>			
<b>Mower Attachments - Continued</b>			
1693284			
Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
1693419			
Arbor .....	1657044		6521BR
P.T.O. ....	1713515		6458BR
1693464			
Arbor .....	1716854		6643BR
1693527			
Arbor .....	1719911		68117
1693558			
Arbor .....	1716854		6643BR
1693560			
Arbor .....	1721532		6798BR
1693585			
Arbor .....	1721533		6856
1693631			
Arbor .....	1671076		6765BR
P.T.O. ....	1722039		6525BR
1693706			
Drive .....	1720932		6737
1693793			
Arbor .....	1716854		6643BR
1693826			
Drive .....	1719819		6434BR
<b>Snow Thrower Attachments</b>			
1691521			
Drive; 1995-1987 .....	1703466		6484BR
1691522			
Drive; 1990-1987 .....	1703466		6484BR
<b>Thatcher Attachments</b>			
<b>300 Series; 400 Series</b>			
Drive .....	2027624		6996
<b>Tiller Attachments</b>			
1690039			
Drive .....	105340		6996
1691277			
Drive - Rear .....	1673667		6895
<b>Rotary</b>			
Belt; W/30" Deck .....	2087648		6872
<b>Vacuum Attachments</b>			
<b>700 Series</b>			
Blower; W/61" Belt O.C. ....	2027102	2610	6861
Blower; W/70" Belt O.C. ....	2027134		6870
Blower; W/77" Belt O.C. ....			6877
P.T.O. ....	2026755		6839
1690503			
Drive .....	1665706		6839
P.T.O. ....	1713549		6478BR
1690990			
Fan .....	1677468		6965
<b>AMERICAN HARDWARE</b>			
<b>Mower Attachments</b>			
09410			
Belt; W/56" Belt O.C. ....	7540230		6755BR
Belt; W/74" Belt O.C. ....	7540293		6501BR
<b>ARIENS</b>			
<b>Mower Attachments</b>			
<b>26" Rotary Mower</b>			
Belt .....	34X92		6945

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>30" Rotary Mower</b>			
Belt .....	72050		6944
<b>32" Rotary Mower</b>			
Belt .....	34X101		6949
<b>35-10M</b>			
Spindle .....	34X102		6936
<b>38" Rotary Mower</b>			
Belt; W/53" Belt O.C. ....	072038		6853
Belt; W/69" Belt O.C. ....	072052		6969
Mower Drive; W/47" Belt O.C. ....	72118		6847
<b>42" Mower Deck</b>			
Belt; W/96" Belt O.C. ....	072139		6896
<b>48" Mower Deck</b>			
Belt; W/105" Belt O.C. ....	072081		A103
<b>829001</b>			
Deck .....	072078		A75
<b>831001</b>			
Blade .....	072080		6889
<b>831002</b>			
Blade .....	072081		A103
<b>831011</b>			
Blade .....	072080		6889
<b>831012</b>			
Blade .....	072081		A103
<b>831026</b>			
Blade .....	072113		6865
<b>831028</b>			
Blade .....	072081		A103
<b>831029</b>			
Belt; W/42" Deck .....	72139		6896
<b>831031</b>			
Blade .....	072081		A103
<b>831038</b>			
Belt; W/42" Deck .....	72139		6896
<b>834001; 834002; 834008; 834010; 834011</b>			
Blade .....	072081		A103
<b>834015</b>			
Belt; W/50" Belt O.C. ....	72096		6850
Belt; W/96" Belt O.C. ....	72139		6896
<b>834016</b>			
Blade .....	072081		A103
Eng. To Deck .....	72096		6850
<b>910011</b>			
Spindle .....	72045	3360	6936
<b>924031</b>			
Blade .....	72045	3360	6936
Drive; W/Small Wheel .....	72083		6376
<b>P.T.O. Kits</b>			
<b>731010</b>			
Belt .....	072076		6835
<b>731019</b>			
Belt .....	072111		6834
<b>Rotary Brush Attachments</b>			
<b>824004</b>			
Drive .....	072108		6376
<b>Snow Thrower Attachments</b>			
<b>83260</b>			
Drive .....	072097		6726
<b>831009; 831010</b>			
Belt; W/46" Belt O.C. ....	072095		6846
Belt; W/50" Belt O.C. ....	072096		6850

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ARIENS - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
834006; 834009			
Auger .....	72142		6834
Drive .....	072118		6847
835006			
Blower .....	072121		6834
Mule Drive .....	072120		6379
Tractor To Blower Drive .....	72138		6733
<b>Tiller Attachments</b>			
831005; 831006			
Belt .....	072105		②A35
834005			
Belt .....	072144		6889
<b>Vacuum Attachments</b>			
4210M			
Forward .....	34X105		3V280
Reverse .....	34X104		3V355
831018			
Drive; W/28" Belt O.C.; Ser. No. 000600 & After .....	072048	7280	
Drive; W/72" Belt O.C.; Ser. No. 000600 & After .....	072122		6872
831019			
Drive; W/28" Belt O.C.; Ser. No. 001100 & After .....	072048	7280	
Drive; W/72" Belt O.C.; Ser. No. 001100 & After .....	072122		6872
834012			
Belt; Ser. No. 000101 & After .....	072148		6858
910975			
Forward .....	72060		6828
Reverse .....	72061		6376
<b>AUTOMOTIVE ASSOCIATES</b>			
<b>Mower Attachments</b>			
198-651			
Belt .....	7540113	3480	6948
198-761			
Blade .....	7540125		6428BR
<b>BEEFCO</b>			
<b>Mower Attachments</b>			
17-060-711			
Spindle - Left & Right .....			5VX710
17-072-711			
Spindle - Left & Right .....			5VX850
<b>BOBCAT</b>			
<b>Mower Attachments</b>			
932400; 932402			
Blade Drive .....	38462		6446BR
P.T.O.; W/Gear Drive .....	2308141		6406BR
P.T.O.; W/Variable Speed Drive .....	38463		6962
933400; 933600			
Blade Drive .....	38389		7040BR
P.T.O.; W/Gear Drive .....	38463		6962
P.T.O.; W/Variable Speed Drive .....	38470		6964
934400			
Blade Drive .....	38440		6702BR
P.T.O.; W/Gear Drive .....	38442		6527BR
P.T.O.; W/Variable Speed Drive .....	38439		6630BR
934600			
Blade Drive .....	38440		6702BR
935400			
Blade Drive .....	38030N		6703BR
P.T.O.; W/Gear Drive .....	38362		6838BR
P.T.O.; W/Variable Speed Drive .....	38291		6972

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOBCAT - Continued</b>			
<b>Mower Attachments - Continued</b>			
936400			
Blade Drive .....	38331		6584BR
M214SP2			
J.S. To Traction .....	78031N		6433BR
<b>Snow Thrower Attachments</b>			
<b>Snow Blower</b>			
Belt; For Model T24N .....		3430	6943
<b>BOLENS</b>			
<b>Mower Attachments</b>			
15FH; 20HD; 21HD			
Belt .....		2300	6830
60-01; 60-02; 60A-03			
Belt .....	1108455	2220	6822
155; 200; 220; 230			
Belt .....		2300	6830
466-01			
Blade; For Model 35AB .....	1705034		6835
Drive; For Model 35AB .....	1705034		6835
Eng. To Versamatic .....	1705033	2220	6822
15100			
Belt; W/28" Deck; W/62" Belt O.C. ....			6862
15100-01			
Belt; W/28" Deck; W/57" Belt O.C. ....	1721995		6857
15100-02			
Belt; W/28" Deck; W/54" Belt O.C. ....			6854
15101			
Blade .....			6875
Drive; W/32" Deck .....	1732582		6831
15101-01; 15101-02			
Drive .....			6875
P.T.O. ....	1721967		6852
15101-07			
Drive; Ser. No. 0400101 Thru 0599999 .....			6875
15108-01			
Drive .....	1716557	2850	6885
P.T.O. ....			6851
15114			
Belt; W/38" Deck .....	1716557	2850	6885
Blade .....			6875
Drive; W/32" Deck .....	1732582		6831
15115			
Blade .....			6875
Drive; W/32" Deck .....	1732582		6831
P.T.O. ....	1737459		6859
15174			
Blade; W/38" Deck .....	1716557	2850	6885
P.T.O.; W/38" Deck .....	1737574		6854
15401			
Belt; For Models 15F, 152, 153, 154 .....	1108461		6828
Belt; For Models 15FH, 20HD, 21HD, 155, 200, 220, 230 .....		2300	6830
15423-01			
Blade .....	1705034		6835
Drive; For Models 15F, 153, 154; W/21" Rotary Mower .....	1108461		6828
Drive; For Models 15FH, 155 .....	1108462	2290	6829
15434-02			
Blade - Left .....	1108473		6840
Blade - Right .....	1108466		6833
Drive; For Models 15FH, 155 .....	1108462	2290	6829
Drive; W/30" Belt O.C. ....	1108539	3300	6930
15446-01			
Blade .....	1705034		6835



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>15446-01 - Continued</b>			
Drive; For Models 15F, 153, 154; W/21"			
Rotary Mower .....	1108461		6828
Drive; For Models 15FH, 155 .....	1108462	2290	6829
<b>16402</b>			
Belt; For Models 15F, 152, 153, 154 .....	1108461		6828
Belt; For Models 15FH, 20HD, 21HD, 155, 200, 220, 230 .....		2300	6830
<b>17428-02; 17429-01; 17429-02</b>			
Belt .....	1108485	2520	6852
<b>18001-01; 18001-02; 18006-01; 18006-02</b>			
Drive .....			6875
P.T.O. ....			6863
<b>18007</b>			
Belt; W/38" Deck .....	1716557		6885
<b>18007-01</b>			
Drive .....	1716557	2850	6885
P.T.O. ....			6862
<b>18048-01; 18048-02</b>			
Blade .....	1718653		A128
<b>18049</b>			
Blade .....	1718653		A128
Drive .....	1724943		A136
<b>18049-01; 18049-02</b>			
Blade .....	1718653		A128
<b>18071</b>			
Belt .....	1726723		A133
<b>18110</b>			
Blade .....	1725502		A144
<b>18300</b>			
Blade; W/42" Deck .....	1728133		6892
Drive; W/B. & S. Eng. ....	1741576		6881
Drive; W/Tecumseh Eng. ....	1726701		6877
<b>18301</b>			
Blade; W/42" Deck .....	1736903		68100
Drive; W/B. & S. Eng. ....	1741577		6883
Drive; W/Tecumseh Eng. ....	1739080		6879
<b>18415-01; 18416-01; 18416-02; 18417-01; 18418-01; 18418-02</b>			
Belt; W/32" Deck .....			6875
<b>18418-03</b>			
Drive; Ser. No. 0400101 Thru 0599999 .....			6875
<b>18420-01; 18421-01; 18422-01; 18423-01</b>			
Drive .....	1185651		A112
<b>18446-01; 18446-02; 18449-01; 18449-02; 18449-04; 18449-05</b>			
Belt; W/32" Deck .....			6875
<b>18457-01; 18457-02; 18457-04; 18458; 18458-02</b>			
Drive .....	1185651		A112
<b>19101-01; 19101-02; 19101-03</b>			
Blade .....	1715213		6861
P.T.O. ....			6853
<b>19102-01; 19102-02</b>			
Blade .....			6875
P.T.O. ....	1717861		6856
<b>19107-01</b>			
Blade .....	1715213		6861
P.T.O. ....			6853
<b>19108-01</b>			
Blade .....			6875
P.T.O. ....	1717861		6856
<b>19209; 19210; 19211</b>			
Drive .....	1724943		A136

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>19303; 19303-01; 19303-02</b>			
Belt; W/32" Deck .....			6875
<b>19307; 19307-01; 19307-02; 19307-03</b>			
Belt; W/38" Deck .....	1716557	2850	6885
<b>19308</b>			
Belt; W/32" Deck .....			6875
<b>19342-01; 19342-02; 19343-01</b>			
Drive .....	1185651		A112
<b>19601-01; 19601-02</b>			
Belt .....			6860
<b>20042S</b>			
Blade; W/42" Deck .....	1736903		68100
P.T.O.; W/42" Deck .....	1744493		6868
<b>20425-01; 20426-01; 20427-01</b>			
Belt .....	1707640	2215	
<b>30036S</b>			
Deck .....	1746823		68105
<b>30042R; 30042S</b>			
Deck .....	1743875		A158
<b>31036S</b>			
Deck .....	1746823		68105
<b>51042S</b>			
Belt; W/36" Deck .....	1746823		68105
<b>1724148</b>			
P.T.O.; W/48" Deck .....	1721967		6852
<b>1748274</b>			
Drive; W/60" Deck .....	1724943		A136
<b>1750842</b>			
Drive; W/48" Deck .....	1724943		A136
<b>RM419-01; RM419-02; RM419-03; RM422-02; RM424-01</b>			
Belt .....	1108456	2230	6823
<b>P.T.O. Kits</b>			
<b>18309; 18309-04; 18309-05</b>			
Belt .....			6838
<b>18318</b>			
Belt; W/B. & S. Eng. ....			6838
Belt; W/Tecumseh Eng. ....	1742385		6372
<b>Sicklebar Attachments</b>			
<b>21310-02; 21311-02</b>			
Belt; For Models 20HD, 200 .....	1108473		6840
Belt; For Models 21HD, 220, 230 .....	1108470	2370	6837
<b>A302B; A302B-01</b>			
Belt; For Models 15F, 15FH .....	1108552	3430	6943
<b>B303; B304</b>			
Belt; Gardener .....	1108562	3530	6953
<b>BR340; BR342</b>			
Belt; Gardener; W/B. & S. Eng. ....	150173	3560	6956
Belt; Gardener; W/Wisconsin Eng. ....	150168	3590	6959
<b>HD310-01; HD311-01</b>			
Belt; For Models 20HD, 200 .....	1108473		6840
Belt; For Models 21HD, 220, 230 .....	1108470	2370	6837
<b>R308; R308-01</b>			
Belt; For Models 35AA, 35AB .....	1108455	2220	6822
<b>S309; S309-01</b>			
Belt; For Model 10 Series .....		2310	6831
<b>Snow Thrower Attachments</b>			
<b>36"</b>			
Lower Belt .....	212261		6887
Upper Belt .....	37756		6856

# LAWN ATTACHMENTS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BOLENS - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
<b>38"</b>			
Belt; For Models GT1400, GT1600 .....	1746823		68105
<b>10136</b>			
Eng. To J.S. ....	37756		6856
J.S. To Snow Thrower .....	212261		6887
<b>15104</b>			
Drive .....	1722523		6849
<b>15512-01</b>			
Belt; For Model 155 .....	1711844		6836
Belt; For Models 153, 154 .....	1705326	2370	6837
<b>15512-02</b>			
Belt; For Models 153, 154, 155 .....	1108547	3380	6938
<b>18002-01; 18002-02; 18002-03</b>			
Drive .....			6841
<b>18148</b>			
Blade .....	1728133		6892
P.T.O.; W/B. & S. Eng.; W/77" Belt O.C. ....	1726701		6877
P.T.O.; W/Tecumseh Eng.; W/81" Belt O.C. ....	1742385		6372
<b>20510-01</b>			
Belt .....	1108461		6828
<b>22513-02; 22513-03</b>			
Belt; For Models 220, 230, 231, 232, 233, 234 .....	1712687	2475	
<b>A505B; A505B-01</b>			
Drive To Countershaft .....	1108576	3670	6967
Eng. To Drive; For Models 15F, 15FH .....	1108554	3450	6945
<b>F505-01</b>			
Belt; For Models 15F, 15FH .....	1108466		6833
Drive .....	1108474	2410	6841
Eng.; For Models 20HD, 21HD, 220, 230 ...	1108461		6828
<b>RM509-01</b>			
Belt; For Models 60, 60A03 .....			6828
Belt; For Models 60-01, 60-02 .....	1108462	2290	6829
<b>S504; S504-01</b>			
Belt; For Model 10 Series .....	1108470	2370	6837
<b>Sprayer Attachments</b>			
<b>15652-03</b>			
Belt .....	1108501	2680	6868
<b>M652-01</b>			
Belt .....	1108481	2480	6848
<b>M652-02</b>			
Belt .....	1108476	2430	6843
<b>Tiller Attachments</b>			
<b>18608</b>			
Belt; Ser. No. 0100101 Thru 0199999 .....	1745371		6854
<b>20326</b>			
Secondary .....			6840
<b>23609-01</b>			
Belt; For Models 21HD, 220, 230 .....	1709698		6943
<b>23609-02</b>			
Belt; For Models 21HD, 220, 230 .....	1711845		6944
<b>51042R</b>			
Belt; W/42" Tiller .....	1746823		68105
<b>RM606-01; RM606-02; RM606-03</b>			
Belt; For Models 60-03, 60A03 .....	1108461		6828
Belt; W/29" Belt O.C. ....	1108462	2290	6829
<b>S605</b>			
Belt .....	1108475		6842

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>BROUWER</b>			
<b>Mower Attachments</b>			
<b>13C850</b>			
Belt; W/33" Belt O.C. ....			③6833
<b>Left Mid Reel Deck; Right Mid Reel Deck</b>			
Belt; W/40" Belt O.C. ....			③6840
<b>Vacuum Attachments</b>			
<b>BV138</b>			
Blower .....			②6950
<b>BUNTON</b>			
<b>Mower Attachments</b>			
<b>633003; 633400</b>			
Blade Drive .....	38389		7040BR
P.T.O. ....	38463		6962
<b>634003; 634400</b>			
Blade Drive .....	38440		6702BR
P.T.O. ....	38442		6527BR
<b>635400</b>			
Blade Drive .....	38030N		6703BR
P.T.O. ....	38362		6838BR
<b>636400</b>			
Blade Drive .....	38331		6584BR
<b>636406; 636406A</b>			
Blade Drive .....	128003		6485BR
P.T.O. ....	2721255		6812BR
<b>655202</b>			
Blade Drive .....	2188176		6574BR
P.T.O. ....	2188175		6721BR
<b>656102</b>			
Blade Drive .....	128003		6485BR
P.T.O. ....	2188134		6480BR
<b>BUSH HOG</b>			
<b>Mower Attachments</b>			
<b>412; 412A; 412C; 412G; 412SA</b>			
P.T.O.; For 42" Models .....	918		B144
<b>2001</b>			
P.T.O.; For 60" Models; W/103" Belt O.C. ..	12731		B100
P.T.O.; For 60" Models; W/127" Belt O.C. ..	12730		B124
P.T.O.; For 60" Models; W/147" Belt O.C. ..	918		B144
P.T.O.; For 60" Models; W/161" Belt O.C. ..	12728		B158
P.T.O.; For 60" Models; W/165" Belt O.C. ..	12727		B162
<b>ATH600</b>			
Blade Drive .....	88667		6599BR
<b>ATH720</b>			
Blade Drive .....	88843		6892BR
<b>RDTH60</b>			
Blade Drive .....	88667		6599BR
<b>RDTH72</b>			
Blade Drive .....	88843		6892BR
<b>TD-1100</b>			
Blade Drive .....	96814		6665BR
<b>TD-1500; TD-1700</b>			
Blade Drive; W/60" Deck .....	88667		6599BR
Blade Drive; W/72" Deck .....	88843		6892BR
<b>CASE, J.I.</b>			
<b>Mower Attachments</b>			
<b>38" Rotary</b>			
Drive; For Model 130 .....	A70226		6962
Drive; For Models 220, 222 .....	C14893		3V670
Spindle; For Model 130 .....	A70227		6868
<b>44" Rotary</b>			
Drive; For Model 130 .....	A70296		6964
Drive; For Model 180 .....	A70525		6961
Drive; For Models 220, 222 .....	C14893		3V670

②Two Required ③Three Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CASE, J.I. - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>44" Rotary – Continued</b>			
Spindle; For Model 130 .....	A70304		6882
Spindle; For Model 180 .....	A70304		6882
Spindle; For Models 220, 222 .....	C10919		3V750
Spindle; For Models 442, 444 .....	C10919		3V750
<b>E38; E44; E44R; E44T; F42; F44</b>			
Blade .....	C23811		3V750
<b>F46</b>			
Blade .....	C22708		6880
Drive .....	C23810		6869
<b>G40</b>			
Blade .....	C23810		6869
Drive .....	C23805		6866
<b>G41</b>			
Drive; For Models 107, 117 .....	C15411		6892
<b>G44</b>			
Blade .....	C22707		6876
Drive; For Models 220, 222 .....	C23804		6867
Drive; For Models 442, 444 .....	C23806		6870
<b>G46</b>			
Blade .....	C22708		6880
Drive; For Models 220, 222 .....	C23804		6867
Drive; For Models 442, 444 .....	C23806		6870
<b>H40</b>			
Blade .....	C16093		6869
Eng. To Deck .....	C22707		6876
<b>H44</b>			
Blade .....	C16094		6876
<b>H46</b>			
Blade .....	C14965		6880
Eng. To Deck .....	C22707		6878
<b>H50; H54</b>			
Deck .....	C22707		6878
<b>J40</b>			
Blade .....	C16093		6869
Eng. To Deck .....	C23808		6873
<b>J44</b>			
Blade .....	C16094		6880
<b>J45</b>			
Belt .....	C23808		6873
<b>J46</b>			
Blade .....	C14965		6880
<b>J48; J50; J54; K45; K46; K48</b>			
Belt .....	C23808		6873
<b>Snow Thrower Attachments</b>			
<b>C36</b>			
Secondary Drive; For Model 130 .....	C11116	3460	6946
<b>C36R</b>			
Secondary Drive; For Model 180 .....	C10510		3V450
<b>C36S</b>			
Primary Drive; For Model 130 .....			6939
Secondary Drive; For Model 130 .....	C11116	3460	6946
<b>C48S</b>			
Secondary Drive; For Model 180 .....	C10510		3V450
<b>CT36</b>			
Secondary Drive; For Model 130 .....	C11116	3460	6946
<b>CT36R</b>			
Secondary Drive; For Model 180 .....	C10510		3V450
<b>CT36S</b>			
Primary Drive; Colt Delux, Colt Super .....			6939
Secondary Drive; Colt Delux, Colt Super ....	C11116	3460	6946

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CASE, J.I. - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
<b>CT48S</b>			
Secondary Drive; Colt Rancher, Colt Super H .....	C10510		3V450
<b>D48S</b>			
Secondary Drive; Colt 2110 .....	C11116	3460	6946
<b>F80; F84; G80</b>			
Primary Drive; For Models 220, 222, 442, 444 .....	C14116		6841
<b>G81</b>			
Primary Drive .....	C15337		6884
<b>G84</b>			
Primary Drive; For Models 220, 222, 442, 444 .....	C14116		6841
<b>H80</b>			
Primary Drive; For Models 220, 222 .....	C16498		6876
<b>H84</b>			
Primary Drive; For Models 220, 222 .....	C16498		6876
Primary Drive; For Models 442, 444 .....	C16499		6881
<b>J80</b>			
Primary Drive; For Models 210, 220, 222, 224 .....			6877
Primary Drive; For Models 444, 446 .....	C23950		6882
<b>J81</b>			
Primary Drive; For Models 108, 110, 118 ...	C23950		6882
<b>J84</b>			
Primary Drive; For Models 210, 220, 222, 224 .....	C23949		6877
Primary Drive; For Models 444, 446 .....	C23950		6882
<b>K80</b>			
Primary Drive; For Models 220, 222, 224 ...	C23538		6875
Primary Drive; For Models 444, 446, 448 ...	C23539		6881
<b>K81</b>			
Primary Drive; For Models 108, 110, 118 ...	C23950		6882
<b>K84; L80</b>			
Primary Drive; For Models 220, 222, 224 ...	C23538		6875
Primary Drive; For Models 444, 446, 448 ...	C23539		6881
<b>L81</b>			
Primary Drive; For Models 108, 110, 118 ...	C23950		6882
<b>L84</b>			
Primary Drive; For Models 220, 222, 224 ...	C23538		6875
Primary Drive; For Models 444, 446, 448 ...	C23539		6881
<b>R82</b>			
Primary Drive; For Models 108YT, 111YT, 114YT, 116YT .....	C29680		6880
<b>SB36</b>			
Secondary Drive; Colt 2110 .....	C11116	3460	6946
<b>SB48</b>			
Secondary Drive; Colt 2110 .....	C11116	3460	6946
Secondary Drive; Colt 2310, Colt 2510, Colt 2712 .....	C11116	3460	6946
<b>Tiller Attachments</b>			
<b>J72</b>			
Belt; W/71" Belt O.C. ....	C19161		6871
<b>COAST TO COAST</b>			
<b>Snow Thrower Attachments</b>			
<b>706-5; 716-3</b>			
Belt .....	7540113	3480	6948
<b>CONTINENTAL BELTON</b>			
<b>Mower Attachments</b>			
<b>KTA54</b>			
Hood .....			69100
<b>KTR48</b>			
Hitch .....	KTR131120		B116

Lawn & Garden Equipment

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>CONTINENTAL BELTON - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>KTR48 - Continued</b>			
Hood .....			69100
<b>KTR60GA</b>			
Hitch; W/123" Belt O.C. ....		B120	
Hitch; W/131" Belt O.C. ....		B128	
Hitch; W/139" Belt O.C. ....	KTR131140	B136	
Hitch; W/143" Belt O.C. ....		B140	
Hitch; W/147" Belt O.C. ....	KTR131148	B144	
Hood; W/115" Belt O.C. ....	KTR131116	B112	
<b>MWR48</b>			
Hood .....	KTR131116	B112	
<b>MWR60</b>			
Hood .....	KTR131136	B133	
<b>COUNTRY CLIPPER</b>			
<b>Lawn Mower Attachments</b>			
<b>4200</b>			
Blade .....			6896
<b>CUB CADET</b>			
<b>Mower Attachments</b>			
<b>328; 337</b>			
Blade .....	7543026		6860
<b>357</b>			
Blade; W/38" Deck .....	7543002	6872	
Deck; W/38" Deck .....	7543001	7072BR	
<b>358; 359; 360</b>			
Deck .....	7543003	6614BR	
<b>361</b>			
Deck; W/50" Deck .....	7543006	6714BR	
<b>363</b>			
Blade; W/38" Deck .....	7543036	6847BR	
<b>374</b>			
Deck; W/60" Deck .....	7543023	6994	
<b>392</b>			
Blade; W/44" Deck .....	7543027	6886	
Deck; W/44" Deck .....	7543029	6620BR	
<b>441</b>			
Blade; W/38" Deck .....	7543036	6847BR	
Deck; W/38" Deck .....	7543029	6620BR	
<b>446</b>			
Deck; W/46" Deck .....	7543029	6620BR	
<b>Lawn Tractor</b>			
Belt .....	7543029	6620BR	
Spindle; W/36" Deck .....	7543026	6860	
Spindle; W/44" Deck .....	7543027	6886	
<b>Snow Thrower Attachments</b>			
<b>45"</b>			
Belt; W/2-Stage Blower Attachment .....	7540284		6941
<b>350</b>			
Auger; W/40" Auger .....	7540330	6890	
P.T.O. Drive; W/40" Auger .....	7540352	6848	
<b>450</b>			
Auger; W/45" Auger .....	7540340	6984	
<b>Tiller Attachments</b>			
<b>400</b>			
Drive; W/8 H.P. Eng. ....	7540253		6843
<b>443</b>			
Rear P.T.O. Kit .....	7543012		②6832
<b>DYNAMARK</b>			
<b>Edger Attachments</b>			
<b>PA259A; PA259B</b>			
Belt; For Motor Arm .....	2363	2440	

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>DYNAMARK - Continued</b>			
<b>Edger Attachments - Continued</b>			
<b>PA261; PA261A</b>			
Double Pulley To Quill; For Motor Arm .....	RM2543		6828
Eng. To Double Pulley; For Motor Arm .....	PA8408	2220	6822
<b>Mower Attachments</b>			
<b>1425</b>			
Cutter Bar; W/42" Rotary Mower .....	1501000		6890
P.T.O.; W/42" Rotary Mower .....	1501001		6463BR
<b>1430 Tiller Adaptor</b>			
Drive .....	1501105		6951
<b>13442 Kit</b>			
Blade; W/82" Belt O.C. ....	48044		6454BR
<b>13443 Kit</b>			
Blade; W/71" Belt O.C. ....			6971
<b>540400</b>			
Blade; For Model 5286; W/92" Belt O.C. ....	527711M1		6892
Blade; W/98" Belt O.C. ....			6898
Deck; W/50" Belt O.C. ....	511277M2		6850
Deck; W/53" Belt O.C. ....			6853
<b>14180000</b>			
Blade; For Model 1014; W/92" Belt O.C. ....	527711M1		6892
Blade; W/90" Belt O.C. ....	15010000		6890
<b>53810100</b>			
Deck .....	25883		6943
<b>Snow Thrower Attachments</b>			
<b>PA263A</b>			
Belt; For Motor Arm .....	PA8408	2220	6822
<b>Tiller Attachments</b>			
<b>1460-0</b>			
Belt; For Motor Arm .....	PA8271		6827
<b>5419</b>			
Belt .....	514806M1		6835
<b>PA260A</b>			
Belt; For Motor Arm .....	PA8271		6827
<b>EDNEY</b>			
<b>Mower Attachments</b>			
<b>Estate Mower</b>			
Deck .....	A105		68107
<b>ENGINEERING PRODUCTS</b>			
<b>Hyd. Pump Attachments</b>			
<b>Side Mounted Pump</b>			
Belt; 1974 & Older .....	810000		6831
<b>Top Mounted Pump</b>			
Belt; 1975 & Newer .....	810025		6825
<b>Sprayer Attachments</b>			
<b>35" Deck</b>			
Belt .....	810000		6831
<b>EXMARK</b>			
<b>Mower Attachments</b>			
<b>FMD-52</b>			
Cross Deck .....	603576		6480BR
Eng. To Deck; Ser. No. 115000 & After .....	543749		6649BR
Eng. To Deck; Ser. No. 83999 & Before .....	543898		6991
Eng. To Deck; Ser. No. 84000 & After .....	543028		6649BR
<b>FMD-60</b>			
Cross Deck .....	603045		6928BR
Eng. To Deck; Ser. No. 89999 & Before .....	543521		6987
Eng. To Deck; Ser. No. 90000 & After .....	543523		6839BR
<b>FMD-523</b>			
Cross Deck .....	603576		6480BR
Eng. To Deck; Ser. No. 115000 & After .....	543749		6649BR

②Two Required





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>EXMARK - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>FMD-603</b>			
Cross Deck .....	603045		6928BR
Eng. To Deck; Ser. No. 115000 & After .....	543523		6839BR
<b>Vacuum Attachments</b>			
<b>651361</b>			
Drive .....	653332		6545BR
<b>651446</b>			
Drive .....	653438		6839
<b>654359; 654360</b>			
Drive .....	653332		6545BR
<b>LHPUV52</b>			
Belt; Lazer Z HP; W/52" Deck .....	653438		6839
Drive .....	653333		6565BR
<b>LHPUV4448</b>			
Drive .....	653332		6545BR
<b>FERRIS INDUSTRIES, INC.</b>			
<b>Mower Attachments</b>			
<b>4000/72</b>			
Deck; Ser. No. 101 Thru 375 .....	22439		6771BR
Deck; Ser. No. 376 & After .....	5022854		6935BR
<b>5000/72</b>			
Deck .....	22439		6771BR
<b>FORD</b>			
<b>Hyd. Lift Attachments</b>			
<b>Gear Tractors</b>			
Belt .....	343092		6726
<b>Hydrostatic Tractors</b>			
Belt .....	343093		6728
<b>Mower Attachments</b>			
<b>09GN-2057</b>			
Mower Drive; W/30" Deck .....	240773		6874
<b>09GN-3658</b>			
Center .....	235955		6739
Drive .....	235956		6880
<b>09GN-3659</b>			
Drive .....	11793		6989
<b>09GN-3661</b>			
Deck .....	234292		6993
Drive .....	11793		6989
<b>09GN-3662</b>			
Blade; W/48" Deck .....	11792		6996
Deck .....	234292		6993
<b>09GN-3674</b>			
Primary; W/36" Snow Thrower .....	210752		6870
<b>09GN-3682</b>			
Blade; W/42" Deck .....	11793		6989
Drive; W/42" Deck; W/50" Belt O.C. ....	235000		6950
Drive; W/89" Belt O.C. ....	11793		6989
<b>09GN-3683</b>			
Blade; W/42" Deck .....			6996
Drive; W/42" Deck .....	237685		6948
<b>09GN-3699</b>			
Blade; W/38" Deck .....	213676		6885
<b>09GN-3700</b>			
Blade; W/38" Deck .....	237738		6886
<b>30" Reel Mower</b>			
Primary .....	343104		6843
Secondary .....	343105		6842
<b>9524; 9528; 9594</b>			
Blade; W/34" Rotary Mower .....	329183		6890

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>FORD - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>9732; 9737</b>			
Blade Drive; W/36" Rotary Mower .....	325877		6859
Deck; W/36" Rotary Mower .....	331599		6868
<b>9788</b>			
Blade; W/50" Rotary Mower .....	330503		6897
Deck; W/50" Rotary Mower .....	328821		6883
<b>9789; 9826; 9835</b>			
Blade; W/42" Rotary Mower .....	328821		6883
Deck; W/42" Rotary Mower .....	328891		6377
<b>9838</b>			
Blade; W/50" Rotary Mower .....	330503		6897
Deck; W/50" Rotary Mower .....	328892		6883
<b>9607441</b>			
Deck; W/42" Deck .....	235000		6950
Drive; W/42" Deck .....	11793		6989
<b>9607442</b>			
Deck .....	11792		6996
<b>9607443</b>			
Belt; W/89" Belt O.C. ....	11793		6989
<b>9607444</b>			
Belt; W/93" Belt O.C. ....	234292		6993
Belt; W/96" Belt O.C. ....	11792		6996
<b>Reel Mower</b>			
Primary; For Models LGT100, LGT120 .....	343104		6843
Secondary; For Models LGT100, LGT120 ..	343105		6842
<b>P.T.O. Attachments</b>			
<b>540 RPM</b>			
Belt .....	343197		6886
<b>Snow Thrower Attachments</b>			
<b>9533; 9577; 9646</b>			
Belt .....	545294		6864
<b>9682</b>			
Belt .....	344218		6865
<b>9746</b>			
Belt .....	328973		6863
<b>9752</b>			
Belt .....	344218		6865
<b>Snow Thrower</b>			
Belt; For Models LGT145, LGT165 .....	330599		6835
<b>Tiller Attachments</b>			
<b>9724</b>			
Belt .....	326946		6968
<b>9761; 9774; A59724</b>			
Belt .....	343196		6967
<b>Vacuum Attachments</b>			
<b>Vacuums</b>			
P.T.O. ....			6868
<b>GAMBLE SKOGMO</b>			
<b>Mower Attachments</b>			
<b>34" Rotary</b>			
Blade .....	754184		6852
Deck .....	754180		6510BR
<b>190-935A</b>			
Deck .....	7540230		6755BR
<b>196-982A</b>			
Drive .....	754125		6428BR
<b>197-957A</b>			
Blade .....	7540181		7014BR
Deck .....	7540213		6853
<b>197-958A</b>			
Deck .....	7540213		6853

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GAMBLE SKOGMO - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>Red Rider</b>			
Blade - Left .....		2310	6831
Blade - Right .....		2300	6830
<b>Snow Thrower Attachments</b>			
<b>190-930A</b>			
Lower Drive .....	7540236		6885
Upper Drive .....	7540206		6850
<b>194-795A</b>			
Auger .....	754186		6882
Drive .....	754180		6510BR
<b>195-968A; 195-969A</b>			
Belt; W/31" Belt O.C. ....	S610	3310	6931
<b>Tiller Attachments</b>			
<b>190-766A; 19766-0</b>			
Belt .....	7540253		6843
<b>GILSON</b>			
<b>Alternator Attachments</b>			
<b>739; 63585; 63591; 63611</b>			
Eng. To Alt.; W/Twin Cyl. Eng. ....	200416		6932
<b>Broom Attachments</b>			
<b>753</b>			
Belt .....	4816G		6887
<b>Composter Attachments</b>			
<b>63535</b>			
Eng. To Composter .....	17653		6847
<b>63546</b>			
Primary .....	24602		6899
Secondary .....	200414		6883
<b>Mower Attachments</b>			
<b>380R; 380S</b>			
Blade .....	9303	1250	6725
<b>724</b>			
Blade .....	11792	3960	6996
<b>731; 735</b>			
Blade .....	9303	1250	6725
<b>741</b>			
Blade .....	11793		6989
Primary .....	12684		6996
Secondary .....	200624		6980
<b>777</b>			
Eng. To Deck .....	14159		6840
<b>902; 932</b>			
Blade .....	3053		6844
<b>943</b>			
Blade .....	9303	1250	6725
<b>33161-B</b>			
Blade .....	11792		6996
Deck .....	12684		6996
<b>62508; 62511</b>			
Eng. To Deck .....	14159		6840
<b>63500</b>			
Blade .....	9303	1250	6725
<b>63521</b>			
Blade .....	11793	3890	6989
Primary .....	12684		6996
Secondary .....	200624		6980
<b>63522</b>			
Blade .....	11792	3960	6996
<b>63545</b>			
Blade .....	11793	3890	6989
Primary .....	12684		6996
Secondary .....	200624		6980

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>63548</b>			
Blade .....	11792	3960	6996
<b>63549; 63550; 63563</b>			
Blade .....	11793	3890	6989
Primary .....	12684		6996
Secondary .....	200624		6980
<b>63587; 63588</b>			
Blade .....	11793		6989
Eng. To Deck .....	36806		6953
<b>63601</b>			
Blade .....	11793	3890	
Primary .....	12684		6996
Secondary .....	200624		6980
<b>63602</b>			
Blade .....	11793		6989
Primary .....	12684		6996
Secondary .....	200624		6980
<b>63603</b>			
Primary .....	12684		6996
Secondary .....	200624		6980
<b>63609; 63622</b>			
Blade .....	11793		6989
Eng. To Deck .....	36806		6953
<b>63623</b>			
Eng. To J.S. ....	37756		6856
J.S. To Mower .....	209581		6886
<b>63624</b>			
Blade .....	200982		6878
Eng. To Deck .....			6981
<b>63640</b>			
Eng. To Deck .....	213676		6885
<b>63648</b>			
Blade .....			6866
<b>Sicklebar Attachments</b>			
<b>63557; 63571</b>			
Secondary .....			6984
<b>Snow Thrower Attachments</b>			
<b>751</b>			
Eng. To Blower .....	13072		A70
<b>62513</b>			
Primary .....			6854
Secondary .....	209630		6839
<b>62527; 62531</b>			
Eng. To J.S. ....	37756		6856
J.S. To Snow Thrower .....	37756		6856
<b>63504</b>			
Eng. To Blower .....	18263		6844
<b>63528; 63556</b>			
Eng. To Blower .....	13072		A70
<b>63593; 63599</b>			
Eng. To J.S. ....	37756		6856
J.S. To Snow Thrower .....	37756		6856
<b>63604</b>			
Eng. To Blower .....	13072		A70
<b>63605</b>			
Primary .....			6854
Secondary .....	209630		6839
<b>63618</b>			
Eng. To J.S. ....			6856
J.S. To Snow Thrower .....	209581		6886
<b>63619</b>			
Eng. To J.S. ....	37756		6856
J.S. To Snow Thrower .....	209581		6886



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GILSON - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
<b>63620</b>			
Primary .....			6854
Secondary .....	209630		6839
<b>63645</b>			
Eng. To J.S. ....	37756		6856
J.S. To Snow Thrower .....	212261		6887
<b>Tiller Attachments</b>			
<b>746; 782; 63525; 63553; 63558</b>			
Primary .....	12570	3560	6956
Secondary .....	200626		6940
<b>63579</b>			
Traction .....	27093		6847
<b>63606</b>			
Primary .....	12570	3560	6956
Secondary .....	200626		6940
<b>63631</b>			
Traction .....	214170		6858
<b>63639</b>			
Secondary .....			6840
<b>GOODALL</b>			
<b>Mower Attachments</b>			
<b>30RAX Brookwood Reel Mower</b>			
Belt .....	W00662		6837
<b>36RA Rotary Mower</b>			
Belt .....	W00694		6836
<b>GRASSHOPPER</b>			
<b>Mower Attachments</b>			
<b>52"</b>			
Drive .....	382800		6547BR
<b>72"</b>			
Belt .....			②6944
<b>744</b>			
Belt .....	382730		6935
<b>752</b>			
Belt; W/39" Belt O.C. ....	382750		6939
Belt; W/41" Belt O.C. ....	382753		6941
<b>1044</b>			
Belt .....	382730		6935
<b>1052</b>			
Belt; W/39" Belt O.C. ....	382750		6939
Belt; W/41" Belt O.C. ....	382753		6941
<b>1544</b>			
Belt .....	382730		6935
<b>1552</b>			
Belt; W/39" Belt O.C. ....	382750		6939
Belt; W/41" Belt O.C. ....	382753		6941
<b>2044; 2144</b>			
Belt .....	383000		6649BR
<b>5052</b>			
Belt .....	382037		6464BR
<b>6044</b>			
Belt .....	383000		6649BR
<b>6052</b>			
Belt .....	382037		6464BR
<b>6061</b>			
Blade To Blade .....	382049		6592BR
<b>6152</b>			
Belt .....	382037		6464BR
<b>6261</b>			
Blade To Blade .....	382049		6592BR

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAVELY</b>			
<b>Blower Attachments</b>			
<b>17303E1; 17304E1</b>			
Drive; For Convertible Tractor .....	17798P1		6840
<b>Generator Attachments</b>			
<b>Starter Gen.</b>			
Belt; For Convertible Tractor .....			3V400
<b>Gov. Attachments</b>			
<b>Westchester-Gov.</b>			
Belt; For Convertible Tractor .....			6719
<b>Mower Attachments</b>			
<b>30" Wing Reel Mower</b>			
Belt; For Convertible Tractor .....	13472	3300	6930
<b>32" Flail Mower</b>			
Belt; For Convertible Tractor .....	12077		BX38
<b>40" Rotary</b>			
Drive; W/117" Belt O.C.; For Convertible Tractor .....	14673P1		68117
Drive; W/38" Belt O.C.; For Convertible Tractor .....	9240P1		6838
Drive; W/76" Belt O.C.; For Convertible Tractor .....	25129		6876
<b>40" Wing Eng. Driven</b>			
Blade; For Convertible Tractor .....	25129		6876
Main Drive; For Convertible Tractor .....	31912		6849
<b>50" Bladed Top Hat</b>			
Drive; W/127" Belt O.C.; For Convertible Tractor .....	11216		6486BR
Drive; W/46" Belt O.C.; For Convertible Tractor .....			6846
Drive; W/51" Belt O.C.; For Convertible Tractor .....			6951
<b>50" Rotary Mower</b>			
Blade - Left; For Convertible Tractor .....			6949
Blade - Right; For Convertible Tractor .....			6954
<b>50" Wing Mower</b>			
Blade; For Garden Tractor .....	11216		6486BR
Primary; For Garden Tractor .....	23639		B64
Secondary; For Garden Tractor .....	23640		B95
<b>60" Rotary Mower</b>			
Bottom Deck; For Convertible Tractor .....	31383		②6387
<b>72" Rotary Mower</b>			
Blade; For Garden Tractor .....	22068		6869
Drive; For Garden Tractor .....	22069		B148
<b>15459E1</b>			
Eng. To Deck .....	15355P1		6838
<b>15689E1</b>			
Drive .....	9240P1		6838
<b>22013</b>			
Blade .....	22068		6869
<b>31855</b>			
Eng. To J.S. ....	31912		6849
J.S. To Blade .....	25129		6876
<b>895401</b>			
Drive .....	07200424		6665BR
<b>895409</b>			
Drive - Upper .....	07200424		6665BR
<b>Comm. Mower; Front Or Center Mounted</b>			
Drive; W/40" Deck .....	9240P1		6838
<b>Gang Wing Reel Mower</b>			
Belt; For Convertible Tractor .....	13474	3320	6932
<b>MA551</b>			
Drive .....	12077P1		6941
<b>Reel Mower</b>			
Single; For Convertible Tractor .....	M475	3300	6930

Lawn & Garden Equipment

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAVELY - Continued</b>			
<b>Pump Attachments</b>			
<b>Meyers Pump</b>			
Belt; For Convertible Tractor .....		3560	6956
<b>Sicklebar Attachments</b>			
<b>Haban Sicklebar</b>			
Drive; For Convertible Tractor .....	6267		6875
<b>Snow Thrower Attachments</b>			
<b>Snow Thrower</b>			
Fan .....	36880		6834
Trans. ....	26121		3V335
<b>Sprayer Attachments</b>			
<b>Sprayer-Pump</b>			
Agitator .....	A409	3580	6958
Belt; For Convertible Tractor .....	A408	3710	6971
<b>Vacuum Attachments</b>			
<b>36980</b>			
Drive; For Convertible Tractor .....	36987		6872
<b>GRAZER</b>			
<b>Lawn Mower Attachments</b>			
<b>0042T11</b>			
Blade .....	9003003A		6895
Deck .....	9003004		6854
<b>0042T112</b>			
Deck .....	9003004		6854
<b>0042TC11-2000 Series</b>			
Blade; W/48" Belt O.C. ....	9003007		6848
Blade; W/53" Belt O.C. ....	9003006		6853
Deck .....	9003009		6858
<b>0042TCSS</b>			
Blade; W/48" Belt O.C. ....	9003007		6848
Blade; W/53" Belt O.C. ....	9003006		6853
Deck .....	9003004		6854
<b>52" Shaft Drive</b>			
Blade To Blade; W/Notched Belt .....	9003012		BX55
Blade To Blade; W/Wrapped Belt .....	9003017		6958
<b>0052T; 0052TC</b>			
Deck .....	9003004		6854
<b>0052TC11-2000 Series</b>			
Deck .....	9003009		6858
<b>0052TCSS</b>			
Deck .....	9003004		6854
<b>62" Shaft Drive</b>			
Blade To Blade; W/63" Belt O.C. ....	9003021		6963
Blade To Blade; W/68" Belt O.C. ....	9003020		6968
<b>0062TC11</b>			
Dual Deck Drive .....	9003009		6858
<b>0062TCSS</b>			
Deck .....	9003004		6854
<b>72" Shaft Drive</b>			
Blade To Blade; W/78" Belt O.C. ....	9003015		6978
Blade To Blade; W/81" Belt O.C. ....	9003016		6981
<b>G42A12; G52T; G52TC</b>			
Deck .....	9003004		6854
<b>Vacuum Attachments</b>			
<b>42" Deck</b>			
Fan; W/12.5 H.P. Eng.; 1987-1982 .....	9003013		6834
Fan; W/16, 18 H.P. Eng.; 1987-1982 .....	9003010		6835
<b>42T12</b>			
Fan; 1989-1988 .....	9003013		6834
<b>42TCSS</b>			
Fan; 1989-1988 .....	9003012		BX55
<b>52" Deck</b>			
Fan; 1989-1982 .....	9003000		6838

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>GRAZER - Continued</b>			
<b>Vacuum Attachments - Continued</b>			
<b>62" Deck</b>			
Fan; 1989-1982 .....	9003014		6944
<b>HAHN ECLIPSE</b>			
<b>Mower Attachments</b>			
<b>7401 Series; 7402 Series; 7403 Series</b>			
Blade .....	308389		6745
<b>7407 Series</b>			
Eng. To Deck .....	308434		3V600
<b>7408 Series; 7409 Series</b>			
Blade .....	308389		6745
<b>7415 Series</b>			
Eng. To Deck .....	308434		3V600
<b>7424 Series</b>			
Eng. To Deck .....	308457		6841
<b>HEALD</b>			
<b>Mower Attachments</b>			
<b>Mowers</b>			
Clutch .....	203023		6844
Drive .....	203024	2770	6877
<b>Snow Thrower Attachments</b>			
<b>Snow Throwers</b>			
Clutch .....	203025		6895
<b>HOMELITE</b>			
<b>Lawn Revitalizer Attachments</b>			
<b>26</b>			
Drive; For Models T-7, T-8 .....	174364		6849
<b>38</b>			
Drive; For Models T-10, T-12, T-15 .....	105340		6996
<b>Mower Attachments</b>			
<b>32M</b>			
Blade .....	1601520		6870
Eng. To Deck .....	176439		6424BR
<b>34" Mower Deck</b>			
Drive .....	JA392606		6893
<b>35" Mower Deck</b>			
Drive .....	JA992251		6864
<b>36M</b>			
Blade .....	1602157		6873
Eng. To Deck .....	1601520		6870
<b>42M</b>			
Blade .....	1603077		6882
Eng. To Deck .....	1607284		6876
<b>48M</b>			
Blade .....	1603075		6457BR
Eng. To Deck .....			6878
<b>P.T.O. Attachments</b>			
<b>172</b>			
Drive .....	123073		6891
<b>Snow Thrower Attachments</b>			
<b>32"</b>			
Drive .....	108209		6415BR
<b>36"; 42"</b>			
Drive .....	1607416		6869
<b>Tiller Attachments</b>			
<b>30RT</b>			
Drive .....	108505		6870
<b>36RT</b>			
Drive .....	105340		6996



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>HOMELITE - Continued</b>			
<b>Vacuum Attachments</b>			
<b>26"</b> Drive .....	174364		6849
<b>38"</b> Drive .....	105340		6996
<b>173</b> Drive .....	165048		6775BR
<b>INGERSOLL</b>			
<b>Mower Attachments</b>			
<b>J-40</b> Blade; W/69" Belt O.C.; W/38" Blade .....	C23810		6869
Blade; W/71" Belt O.C.; W/38" Blade .....	C23359		6871
<b>J-44</b> Blade; W/71" Belt O.C.; W/44" Blade .....	C23359		6871
Blade; W/76" Belt O.C.; W/44" Blade .....	C22707		6876
<b>J-46</b> Blade; W/71" Belt O.C.; W/48" Blade .....	C23359		6871
Blade; W/80" Belt O.C.; W/48" Blade .....	C22708		6880
<b>K-40</b> Blade; W/69" Belt O.C.; W/38" Blade .....	C23810		6869
Blade; W/71" Belt O.C.; W/38" Blade .....	C23359		6871
<b>K-44</b> Blade; W/71" Belt O.C.; W/44" Blade .....	C23359		6871
Blade; W/76" Belt O.C.; W/44" Blade .....	C22707		6876
<b>K-46</b> Blade; W/71" Belt O.C.; W/48" Blade .....	C23359		6871
Blade; W/80" Belt O.C.; W/48" Blade .....	C22708		6880
<b>L-40</b> Blade; W/69" Belt O.C.; W/38" Blade .....	C23810		6869
Blade; W/71" Belt O.C.; W/38" Blade .....	C23359		6871
<b>L-44</b> Blade; W/71" Belt O.C.; W/44" Blade .....	C23359		6871
Blade; W/76" Belt O.C.; W/44" Blade .....	C22707		6876
<b>L-46</b> Blade; W/71" Belt O.C.; W/48" Blade .....	C23359		6871
Blade; W/80" Belt O.C.; W/48" Blade .....	C22708		6880
<b>L-48</b> Blade; W/50" Belt O.C.; W/44" Blade .....	C27120		6850
Blade; W/76" Belt O.C.; W/44" Blade .....	C22707		6876
<b>M-40</b> Blade; W/69" Belt O.C.; W/38" Blade .....	C23810		6869
Blade; W/71" Belt O.C.; W/38" Blade .....	C23359		6871
<b>M-44</b> Blade; W/71" Belt O.C.; W/44" Blade .....	C23359		6871
Blade; W/76" Belt O.C.; W/44" Blade .....	C22707		6876
<b>M-46</b> Blade; W/71" Belt O.C.; W/48" Blade .....	C23359		6871
Blade; W/80" Belt O.C.; W/48" Blade .....	C22708		6880
<b>M-48</b> Blade; W/50" Belt O.C.; W/44" Blade .....	C27120		6850
Blade; W/76" Belt O.C.; W/44" Blade .....	C22707		6876
<b>N-40</b> Blade; W/69" Belt O.C.; W/38" Blade .....	C23810		6869
Blade; W/71" Belt O.C.; W/38" Blade .....	C23359		6871
<b>N-44</b> Blade; W/71" Belt O.C.; W/44" Blade .....	C23359		6871
Blade; W/76" Belt O.C.; W/44" Blade .....	C22707		6876
<b>N-46</b> Blade; W/71" Belt O.C.; W/48" Blade .....	C23359		6871
Blade; W/80" Belt O.C.; W/48" Blade .....	C22708		6880
<b>Snow Blower Attachments</b>			
<b>112YT</b> Eng. To Auger .....	C29680		6880

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>INGERSOLL - Continued</b>			
<b>Snow Blower Attachments - Continued</b>			
<b>F-80; F-84; G-80; G-84</b> Primary Drive .....	C14116		6841
<b>H-80</b> Primary Drive .....	C16498		6876
<b>H-84</b> Primary Drive; W/76" Belt O.C. ....	C16498		6876
Primary Drive; W/81" Belt O.C. ....	C16499		6881
<b>J-80; J-81; J-84</b> Primary Drive .....	C23950		6882
<b>K-80</b> Primary Drive; W/75" Belt O.C. ....	C23538		6875
Primary Drive; W/81" Belt O.C. ....	C23539		6881
<b>K-81</b> Primary Drive .....	C23950		6882
<b>K-84; L-80</b> Primary Drive; W/75" Belt O.C. ....	C23538		6875
Primary Drive; W/81" Belt O.C. ....	C23539		6881
<b>L-81</b> Primary Drive .....	C23950		6882
<b>L-84</b> Primary Drive; W/75" Belt O.C. ....	C23538		6875
Primary Drive; W/81" Belt O.C. ....	C23539		6881
<b>R-82</b> Primary Drive; W/38" Snow Blower .....	C29680		6880
<b>INTERNATIONAL</b>			
<b>Mower Attachments</b>			
<b>38" Mower Drive</b> Belt .....	473468R2		6872
<b>BB-36</b> Drive .....	475595R1		6827
<b>C-32</b> Primary .....	493649R1		6873
Secondary .....	493650R1		6850
<b>Cadet 75</b> Blade; W/Side Discharge .....			6848
Forward .....	549107R1		6839
Mower .....	549599R1		6854
<b>Cadet 85 Special</b> Blade; W/Side & Rear Discharge .....	106990C1		6845
Forward; W/Side & Rear Discharge .....	549107R1		6839
Mower; W/51" Belt O.C. ....	106465C1		6851
Mower; W/Side & Rear Discharge .....	106991C1		6855
<b>Cadet 95</b> Trans. ....	57842C1		6833
<b>CC-36; CC-42; CW-36</b> Drive .....	475610R1		6728
<b>OA-36; OA-42</b> Drive .....	487043R1		6728
<b>Rotary 2 Spindle</b> Spindle .....	464351R1		6830
<b>Rotary 3 Spindle</b> Spindle; W/44" Mower .....	59701C1		6877
Spindle; W/50" Mower .....	59702C1		6885
<b>Shredder Attachments</b>			
<b>59M</b> Drive .....	596361C1		6830
<b>Snow Thrower Attachments</b>			
<b>QA36; QA42</b> Belt .....	487043R1		3V280
<b>Tiller Attachments</b>			
<b>1; 1A</b> Drive .....	485609R1		3V530

LAWN ATTACHMENTS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JACOBSEN</b>			
<b>Mower Attachments</b>			
59503 Eng. To Mower .....	325887		6859
59504 Eng. To Mower .....	326308		6869
59527; 59589 Blade .....	329193		6890
59656 Clutch .....	307522		6842
Reel Drive .....	316910	2430	6843
59730 Eng. To Mower .....	331876		6869
59787 Blade .....	328821		6883
59827; 59866 Blade .....	330503		6897
Mower .....	328892		6883
59869 Blade .....	392397		B112
Eng. To Deck .....	392433		69100
59890 Drive .....	392410		6841
Chief GT Blade; W/82" Belt O.C.; W/42" Rotary Mower .....	328821		6882
Blade; W/83" Belt O.C.; W/42" Rotary Mower .....	328892		6883
Drive; W/42" Rotary Mower .....	390008		6847
UT32036 Deck .....	JA991488		6873
UT33015 Deck .....	JA992251		6864
<b>P.T.O. Kits</b>			
59542; 59564; 59572 Drive .....	329207		6836
59665 Drive .....	325074	2840	6884
59669 Drive .....	342307	2860	6886
59674 Drive .....	329253		6890
59792; 59825; 59834; 59864 Blade .....	328821		6883
Mower .....	328891		6377
GT Rear P.T.O. Belt; W/Dual Belts .....	392445		②6828
Belt; W/Single Belt .....	330675		6828
<b>Snow Thrower Attachments</b>			
59641 Elbow Drive .....	317735		6742
Main Drive .....	317749		6853
59644 Auger .....	545294	2640	6864
59681 Drive .....	344218		6865
59745 Drive .....	328973		6863
59750; 59751 Drive .....	331594		6832
Trans. ....	328973		6863
59849 Drive .....	330599		6835

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JACOBSEN - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
59892 Drive .....	392410		6841
59895 Drive .....	330599		6835
<b>Tiller Attachments</b>			
59713 Drive .....	326946		6968
<b>Vacuum Attachments</b>			
Vacuums P.T.O. ....			6868
<b>JARI</b>			
<b>Mower Attachments</b>			
Rotary Mower Blade - Left .....	E120	2280	6828
Blade - Right .....	N701	2360	6836
<b>JOHN DEERE</b>			
<b>Mower Attachments</b>			
25 Flail; 25A Flail Drive; W/540 R.P.M. Rotor Drive .....	E51728		TR28570
34" Mid Mount Blade; For Models 60, 70, 100; For Garden Tractor .....	M43569		6850
38" Mid Mount Deck; For Models 110, 112; For Garden Tractor .....	M40223		6532BR
Primary; For Model 200; For Garden Tractor .....	M47766		6508BR
Primary; For Models 110, 112; Ser. No. 100000 & Before; For Garden Tractor .....	M40222		A26
Primary; For Models 110, 112; Ser. No. 100001 & After; For Garden Tractor .....	M45998		6883
Secondary; For Models 110, 112; For Garden Tractor .....	M40224		6857
38" Rotary Blade To Blade; Model No. 110, 112; Ser. No. 100000 & Before .....	M40223		6532BR
Deck; Model No. 110, 112; Ser. No. 100000 & Before .....	M45998		6883
Intermediate Drive; Model No. 110, 112; Ser. No. 3550 & Before .....	M40222		A26
Intermediate Drive; Model No. 110, 112; Ser. No. 3551-100000 .....	M40224		6857
39" Mid Mount Blade; Ser. No. 176558 & Before; For Garden Tractor .....	M45998		6883
Blade; Ser. No. 176559 Thru 212088; For Garden Tractor .....	M47043		6377
Drive; For Garden Tractor .....	M40223		6532BR
Primary; For Garden Tractor .....	M47766		6508BR
39" Rotary Blade To Blade; Model No. 110, 112, 200 Series; Ser. No. 100001-488000 .....	M40223		6532BR
Deck; Ser. No. 176558 & Before; W/83" Belt O.C. ....	M45998		6883
Deck; Ser. No. 176558 & Before; W/84" Belt O.C. ....	M47765		6412BR
Deck; Ser. No. 176559 & After; W/79 3/4" Belt O.C. ....	M47043		6377
Deck; Ser. No. 176559 & After; W/80" Belt O.C. ....	M47766		6508BR
41" Mid Mount Blade; For Garden Tractor .....	M40757		6877
Primary; For Model 317; For Garden Tractor .....	M82721		6888
41" Rotary Blade To Blade; Model No. 120, 140, 300, 312, 314, 317 .....	M40757		6877
Blade To Blade; Model No. 316; Ser. No. 95000 & Before .....	M40757		6877

②Two Required





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>41" Rotary - Continued</b>			
Deck; Model No. 120, 140, 300, 312, 314 ..	M45998		6883
Deck; Model No. 316; Ser. No. 95000 & Before .....	M45998		6883
Deck; Model No. 317 .....	M82721		6888
<b>46" Mid Mount</b>			
Blade To Blade; Model No. 112; Ser. No. 100000 & Before .....	M82734		6860
Blade To Blade; Model No. 120, 140, 300 Series .....	M41668		6533BR
Deck; For Model 112; Ser. No. 100000 & Before .....	AM31159		②6828
Deck; For Model 112; Ser. No. 100001 & After .....	M45998		6883
Deck; For Model 200 Series .....	M41960		6653BR
Deck; Model No. 120, 140, 314 .....	M45254		6887
Deck; Model No. 316; Ser. No. 285000 & Before .....	M45254		6887
Deck; Model No. 316; Ser. No. 285001 & After .....	M82718		6713BR
Deck; Model No. 317, 318 .....	M82718		6713BR
Deck; Model No. 322, 330, 332 .....	M89112		6463BR
<b>47"</b>			
Blade; Ser. No. 205468 & Before; For Garden Tractor .....	M45998		6883
Drive; For Garden Tractor .....	M41960		6653BR
<b>47" Rotary</b>			
Blade To Blade .....	M41960		6653BR
Deck; Ser. No. 205468 & Before; W/83" Belt O.C. ....	M45998		6883
Deck; Ser. No. 205469 & After; W/79 3/4" Belt O.C. ....	M47043		6377
Deck; W/84" Belt O.C. ....	M47765		6412BR
<b>48" Mid Mount</b>			
Blade; Exc. Model 317; For Garden Tractor .....	M45998		6883
Drive; For Garden Tractor .....	M41668		6533BR
Primary; For Models 316, 318; For Garden Tractor .....	M119872		6710BR
Primary; For Models 322, 330, 332; For Garden Tractor .....	M119871		6524BR
<b>48" Rotary</b>			
Blade To Blade; Model No. 120, 140, 300, 312, 314, 317 .....	M41668		6533BR
Blade To Blade; Model No. 316; Ser. No. 95000 & Before .....	M41668		A96
Deck; Model No. 120, 140, 300, 312, 314 ..	M45254		6886
Deck; Model No. 316; Ser. No. 95000 & Before .....	M45254		6886
Deck; Model No. 317 .....	M82718		6713BR
<b>50" 3-Point Hitch Rotary</b>			
Secondary; Model No. 300 Series .....	M41668		6533BR
<b>50" Mid Mount</b>			
Primary; For Models 316, 317, 318; Ser. No. 285001 & After .....	M82718		6713BR
Primary; For Models 322, 330, 332 .....	M89112		6463BR
Primary; Model No. 300, 312, 316; Ser. No. 095000 & Before .....	M45254		6887
Primary; Model No. 314; Ser. No. 285000 & Before .....	M45254		6887
Secondary; For Model 300 Series .....	M41668		6533BR
<b>60"</b>			
Deck; For Garden Tractor .....	M48444		6744BR
<b>350 Sickle</b>			
Belt; W/540 R.P.M. Rotor Drive .....	E58483		C107
<b>450 Sickle</b>			
Belt; W/540 R.P.M. Rotor Drive .....	E58483		C107
Fan .....	M97340		6733
P.T.O. ....	AM35380		6841
<b>762</b>			
Primary; For Lawn Tractor .....			6866
Secondary; For Lawn Tractor .....	M82461		6839

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>JOHN DEERE - Continued</b>			
<b>Snow Blower Attachments</b>			
<b>359</b>			
Drive .....	AM38778		②B42
<b>Snow Thrower Attachments</b>			
<b>32; 32A</b>			
Drive; Ser. No. 400000 & Before .....	M41668		6533BR
<b>36</b>			
Drive; For Models 110, 112 .....	M43586		6868
<b>37</b>			
Drive .....	M45998		6883
<b>37A</b>			
Drive; Ser. No. 110001 & After .....	M44272		6377
<b>38"</b>			
Drive; For Front Mowers .....	M79204		6890
Drive; For Models STX30, STX38 .....	M134268		6874BR
Drive; Ser. No. 400001 & After .....	M134268		6874BR
<b>47" 2 Stage Mid Mount</b>			
Drive; For Model 318 .....	M85442		6844
Drive; For Models 322, 332 .....	M75746		6841
<b>49</b>			
Traction Mount Idler; For Model 317 .....	M82719		6849
Traction Mount Idler; For Models 120, 140, 300, 312, 314, 316 .....	M42485		6846
Traction Mount Idler; For Models 316, 318; Ser. No. 285001 & After .....	M82719		6849
Traction Mount Idler; For Models 322, 330, 332 .....	M91270		6847
<b>338</b>			
Drive .....	M134268		6874BR
<b>Tiller Attachments</b>			
<b>30</b>			
Primary Drive; For Model 110; Ser. No. 100,000 & Before .....	M43489		6857
Primary Drive; For Model 112 .....	M47770		6858
Secondary Drive; Ser. No. 100,000 & Before .....	M41140		BX124
<b>30"</b>			
Primary Drive - Front; For Model 200 Series .....	M84223		6862
<b>31</b>			
Primary Drive; Ser. No. 100001 Thru 118000 .....	M43489		6857
Primary Drive; Ser. No. 118001 & After .....	M47770		6858
Secondary Drive; Ser. No. 100001 & After ..	M47771		B112
<b>33</b>			
Primary; For Model 140; Ser. No. 30000 & Before .....	AM32172		②A33
Primary; For Model 140; Ser. No. 30001 & After .....	AM32636		②A34
Primary; For Models 120, 300 .....	AM32636		②A34
<b>Hydraulic Tiller</b>			
Drive; For Models 420, 430 .....	AM101711		②6825
Optional Drive; For Model 316; Ser. No. 285001 & After; W/25" Belt O.C. ....	AM101711		②6825
Optional Drive; For Model 316; Ser. No. 285001 & After; W/90" Belt O.C. ....	M82718		6713BR
Optional Drive; For Models 318, 330 .....	AM101711		②6825
Primary Drive; For Model 318 .....	M82718		6713BR
Primary Drive; For Models 210, 212, 214, 216; W/38" Tiller .....	M47766		6508BR
Primary Drive; For Models 210, 212, 214, 216; W/46" Tiller .....	M47765		6412BR
<b>Vacuum Attachments</b>			
<b>Vacuums</b>			
P.T.O. ....			6867

Lawn & Garden Equipment

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>KUBOTA</b>			
<b>Mower Attachments</b>			
<b>B425</b>			
Drive .....	7008000656		6892
<b>B445</b>			
Blade .....			6883
Drive .....			6898
<b>B3048</b>			
Blade .....	7008001412		6984
<b>K44</b>			
Blade; For Model B6000E .....	7008000246		A110
Deck; For Model B6000E .....	7008000247		6883
<b>K48</b>			
Blade .....			6890
Drive .....			A120
<b>K60</b>			
Blade .....			6961
<b>L3560</b>			
Blade .....	7008000963		6974
<b>MR4800</b>			
Blade .....	7072134710		6995
<b>RC40; RC40-G</b>			
Blade .....	70713-34770		6984
<b>RC44-42; RC44-G</b>			
Blade .....	70712-34710		6989
<b>RC60-20; RC60-25; RC60-27</b>			
Belt .....	70706-34710		C109
<b>RC60-71H; RC60-82H; RCB60-1</b>			
Blade .....	70722-34710		B108
<b>LAND PRIDE</b>			
<b>Mower Attachments</b>			
<b>AFM4211</b>			
Drive .....	816-142C		6856BR
<b>AFM4214</b>			
Drive .....	816-063C		6800BR
<b>AFM4216</b>			
Drive .....	816-141C		6879BR
<b>FDR1648</b>			
Drive .....	816-142C		6856BR
<b>FDR1660</b>			
Drive .....	816-308C		6858BR
<b>FDR2548</b>			
Drive .....	816-142C		6856BR
<b>FDR2560</b>			
Drive .....	816-308C		6858BR
<b>FDR2584</b>			
Drive .....	816-064C		6769BR
<b>LASTEC</b>			
<b>Mower Attachments</b>			
<b>325EF; Articulator</b>			
Blade - Left Wing .....			6989
Blade - Right Wing .....			6987
<b>LAWN BOY</b>			
<b>Mower Attachments</b>			
<b>63706; 63707</b>			
Deck .....	11793		6989
Drive .....	235000		6950
<b>636675</b>			
Drive .....	245477		6884

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>LAWN ROVR</b>			
<b>Mower Attachments</b>			
<b>Mower</b>			
Belt .....			6877
<b>Rotary Mower</b>			
Spindle .....		2340	6834
<b>MASSEY FERGUSON</b>			
<b>Hyd. Lift Attachments</b>			
<b>Power Lift</b>			
Gen. ....	511485M1	7320	
<b>Mower Attachments</b>			
<b>1691220</b>			
Arbor .....	1656960		6811BR
P.T.O. ....	1666801		6640BR
<b>1691221</b>			
Arbor .....	1657044		6521BR
P.T.O. ....	1713515		6458BR
<b>1691607</b>			
Drive .....	1679913		6745
<b>1691815</b>			
Arbor .....	1716854		6643BR
<b>1691816</b>			
Arbor .....	1721532		6798BR
P.T.O. ....	1601672		6799BR
<b>1692003</b>			
Drive .....	1679914		6749
<b>1692030</b>			
Drive .....	1707956		6739
<b>1692038</b>			
Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
<b>1692172; 1692173</b>			
Drive .....	1719746		6873
<b>1692174</b>			
Drive .....	1719819		6434BR
<b>1692257</b>			
Drive .....	1679914		6749
<b>1692410</b>			
Arbor .....	1713549		6478BR
<b>1692544</b>			
Drive .....	1719746		6873
<b>1692546</b>			
Drive .....	1719819		6434BR
<b>1692589; 1692683</b>			
Arbor .....	1716854		6643BR
<b>1692685; 1692687</b>			
Arbor .....	1721532		6798BR
P.T.O. ....	1601672		6799BR
<b>1692689</b>			
Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
<b>1692716</b>			
Drive .....	1707956		6739
<b>1692858</b>			
Drive .....	1717146		6736
<b>1692882</b>			
Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
<b>1692913</b>			
Arbor .....	1719819		6434BR
<b>1692915</b>			
Arbor .....	1713549		6478BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MASSEY FERGUSON - Continued</b>			
<b>Mower Attachments - Continued</b>			
1692936 Drive .....	1679914		6749
1693079 Arbor .....	1716854		6643BR
1693106 Drive .....	1717146		6736
1693228 Drive .....	1707956		6739
1693236 Arbor .....	1703836		6524BR
P.T.O. ....	1719746		6873
1693284 Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
1693419 Arbor .....	1657044		6521BR
P.T.O. ....	1713515		6458BR
1693464 Arbor .....	1716854		6643BR
1693527 Arbor .....	1719911		68117
1693558 Arbor .....	1716854		6643BR
1693560 Arbor .....	1721532		6798BR
1693585 Arbor .....	1721533		6856
1693631 Arbor .....	1671076		6765BR
P.T.O. ....	1722039		6525BR
1693706 Drive .....	1720932		6737
1693792; 1693793 Arbor .....	1716854		6643BR
1693826 Drive .....	1719819		6434BR
MF7 Rotary Drive .....	518125M1		6840
MF42E Rotary Blade; For Model MF8E; Ser. No. 6001 & After .....	1025557M1	2750	6875
Drive; For Model MF8E; Ser. No. 6000 & Before .....	1025542M1	2500	6850
Drive; For Model MF8E; Ser. No. 6001 & After .....	1030050M1	2490	6849
MF610 Rotary Drive; For Models MF10, MF12 .....	511277M2		6850
<b>P.T.O. Kits</b>			
Front Mounted P.T.O. Belt .....	513790M1		3V900
<b>Snow Thrower Attachments</b>			
1691521 Drive; 1995-1987 .....	1703466		6484BR
MF36E Belt; For Models MF7E, MF8E .....	1029730M1	3630	6963
MF620 Auger; For Models MF10, MF12; Ser. No. 1458-001-585 & Before .....	1029730M1	3630	6963
Drive; For Models MF10, MF12; Ser. No. 1458-001-585 & Before .....	1032843M1		6872
<b>Tiller Attachments</b>			
1690039 Drive .....	105340		6996

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MASSEY FERGUSON - Continued</b>			
<b>Tiller Attachments - Continued</b>			
MF650 Rotary Drive .....	514806M1		6835
<b>Vacuum Attachments</b>			
1690503 Drive .....	1665706		6839
P.T.O. ....	1713549		6478BR
1690990 Fan .....	1677468		6965
<b>MERRY TILLER</b>			
<b>Mower Attachments</b>			
J2 Belt .....	862	2400	6840
J3 Belt .....	1023		6843
J4 Belt .....	862	2400	6840
<b>Sicklebar Attachments</b>			
H-1; H-2; H-3 Belt .....	594		6834
H-4; H-5 Belt .....	1530		6837
<b>MONTGOMERY WARD</b>			
<b>Alternator Attachments</b>			
GIL33060; GIL33259; GIL33435; GIL33438; GIL33439 Eng. To Alt.; W/2-Cyl. Eng. ....	200416		6932
<b>Composter Attachments</b>			
GIL33059 Eng. To Composter .....	17653		6847
GIL33112 Primary .....	24602		6899
Secondary .....	200414		6883
GIL33423 Eng. To Composter .....	200414		6883
GIL33432 Primary .....	24602		6899
Secondary .....	200414		6883
GIL33541 Eng. To Composter .....	24602		6899
GIL63535 Eng. To Composter .....	17653		6847
GIL63607 Primary .....	24602		6899
Secondary .....	200414		6883
<b>Mower Attachments</b>			
G33061 Blade .....	11792	3960	6996
Primary .....	12684		6996
Secondary .....	200624		6980
GIL33142; GIL33147; GIL33151 Blade .....	11793		6989
Primary .....	12684		6996
Secondary .....	200624		6980
GIL33161 Blade .....	11792	3960	6996
Primary .....	12684		6996
Secondary .....	200624		6980
GIL33168; GIL33426 Blade .....	11793		6989
Primary .....	12684		6996
Secondary .....	200624		6980

Lawn & Garden Equipment

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>GIL33427</b>		<b>3960</b>	
Blade .....	11792		6996
Primary .....	12684		6996
Secondary .....	200624		6980
<b>GIL33428</b>			
Blade .....	11793		6989
Primary .....	12684		6996
Secondary .....	200624		6980
<b>GIL33472</b>			
Blade .....	11793		6989
Eng. To Deck .....	36806		6953
<b>GIL33473</b>			
Blade .....	200982		6878
Eng. To Deck .....			6981
<b>GIL33474; GIL33481</b>			
Blade .....	11793		6989
Eng. To Deck .....	36806		6953
<b>GIL33482</b>			
Blade .....	200982		6878
Eng. To Deck .....			6981
<b>GIL33483</b>			
Blade .....	11793		6989
Eng. To Deck .....	36806		6953
<b>GIL33500</b>		<b>3960</b>	
Deck .....	11792		6996
<b>GIL33501</b>			
Deck .....	11793		6989
<b>GIL33504</b>			
Deck .....	12684		6996
<b>GIL33897B</b>			
Belt .....	213676		6885
<b>GIL33947; GIL34497</b>			
Eng. To Deck .....			6866
<b>GIL63640B</b>			
Belt .....	213676		6885
<b>GIL63684</b>			
Blade; W/Electric Clutch .....	239025		6983
Blade; W/Man. Clutch .....	239024		6999
Deck .....	11793		6989
<b>SIM Model 32"</b>			
Cross Deck .....	108175		6856
Spindle .....	108151		6863
<b>SIM1217A</b>			
Spindle .....	108151		6863
<b>SIM1244</b>			
Blade .....	108151		6863
Cross Deck .....	119037		6878
<b>SIM1265B</b>			
Cross Deck .....	108099		6844
Spindle .....	108209		6415BR
<b>SIM1282</b>		<b>1250</b>	
Blade .....	9303		6725
<b>SIM1344</b>		<b>2310</b>	
Belt .....	S1A164		6831
<b>SIM1345</b>			
Blade .....	108151		6863
Cross Deck .....	108300		6842
<b>SIM1346</b>		<b>2330</b>	
Belt .....	S1A119		6833
<b>SIM5098A</b>		<b>2310</b>	
Belt .....	S1A164		6831
<b>SIM5099A</b>		<b>2330</b>	
Belt .....	S1A119		6833

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>TMO Model 42"</b>			
Deck .....	7540181		7014BR
Drive .....	7540180		6510BR
<b>TMO33601A</b>			
Belt; W/44" Deck .....	7540230		6755BR
<b>TMO33602A</b>			
Blade .....	7540260		5716
<b>TMO33604A</b>			
Blade .....	7540293		6501BR
Deck .....	7540230		6755BR
<b>TMO33605A</b>			
Blade .....	7540260		5716
<b>Plow Attachments</b>			
<b>Plow Trac</b>			
Belt .....	504250	<b>3500</b>	6950
<b>Sicklebar Attachments</b>			
<b>GIL3315; GIL33110</b>			
Secondary .....			6984
<b>SIM1355; SIM5637</b>			
Belt .....	S4MA19	<b>2370</b>	6837
<b>SIM33311</b>			
Belt; W/100" Belt O.C. ....	173461		68100
Belt; W/57" Belt O.C. ....	173948		6857
Belt; W/93" Belt O.C. ....			6993
<b>Snow Thrower Attachments</b>			
<b>930</b>			
Belt .....	7540206		6850
<b>GIL33023</b>			
Primary .....			6854
Secondary .....	209630		6839
<b>GIL33053; GIL33224; GIL33430</b>			
Eng. To Blower .....	13072		A70
<b>GIL33431</b>			
Primary .....			6854
Secondary .....	209630		6839
<b>GIL33476</b>			
Eng. To J.S. ....	37756		6856
J.S. To Snow Thrower; W/83" Belt O.C. ....	37757		6883
J.S. To Snow Thrower; W/86" Belt O.C. ....	209581		6886
<b>GIL33506</b>			
Eng. To Blower .....	13072		A70
<b>GIL33523</b>			
Belt .....	200413		6839
<b>GIL33540</b>			
Belt .....	209581		6886
<b>GIL33871</b>			
Eng. To J.S. ....	37756		6856
J.S. To Snow Thrower; W/83" Belt O.C. ....	37757		6883
J.S. To Snow Thrower; W/86" Belt O.C. ....	209581		6886
<b>GIL34471</b>			
Eng. To J.S. ....	37756		6856
<b>SIM1286</b>			
Eng. To Blower; W/44" Belt O.C. ....	18263		6844
Eng. To Blower; W/72" Belt O.C. ....	13072		A70
<b>TMO Model Snow Thrower</b>			
Belt .....	7540185		6849
<b>TMO491</b>			
Eng. To J.S. ....	7540299		6849
J.S. To Drive Pulley .....	7540294		6889
<b>TMO33012</b>			
Belt .....	7540206		6850



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MONTGOMERY WARD - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
<b>TMO33848C</b>			
Eng. To J.S. ....	7540299		6849
J.S. To Drive Pulley .....	7540294		6889
<b>TMO33848E</b>			
Drive .....	7540299		6849
Variator .....	7540294		6889
<b>Tiller Attachments</b>			
<b>GIL33055; GIL33095; GIL33163; GIL33429</b>		3560	6956
Primary .....	12570		6940
Secondary .....	200626		
<b>GIL33498</b>			6858
Eng. To Tiller .....	214170		
<b>GIL33505</b>		3560	6956
Belt .....	12570		
<b>GIL33522</b>			6856
Belt .....	200625		
<b>GIL33895</b>			6840
Secondary .....			
<b>SIM4964; SIM5634 Chor Trac; SIM5634 Power Trac</b>			6855
Belt .....	503855		
<b>TMO746</b>			6852
Belt; W/52" Belt O.C. ....	7540229		6895
Belt; W/95" Belt O.C. ....	7540283A		
<b>TMO766</b>			6843
Belt; W/43" Belt O.C. ....	7540253		
<b>TMO33603A; TMO33603B</b>			6852
Eng. To J.S. ....	7540229		6895
J.S. To Tine .....	7540283		
<b>MOTO-MOWER</b>			
<b>Mower Attachments</b>			
<b>26-6100</b>		2520	6852
Belt .....	1021462		
<b>61-802</b>		1310	6731
Belt .....	5234		
<b>6020; 6020E</b>		2290	6829
Belt; W/29" Belt O.C. ....	1016174		6850
Belt; W/50" Belt O.C. ....	1036030		6860
Belt; W/60" Belt O.C. ....	1022460		7360
Gen. ....	1048684		
<b>6021; 6022</b>		3350	6935
Eng. To J.S. ....	1034685		7360
Gen. ....	1048684		
High Speed Drive .....	1022480		6831
Low Speed Drive .....	1022149		6832
Transaxle; W/60" Belt O.C. ....	1022460		6860
Transaxle; W/62" Belt O.C. ....	1034684		3620
<b>6100; 6700</b>		2520	6852
Belt .....	1021462		
<b>6800</b>		2500	6850
Belt .....	1036030		
<b>7100</b>		2520	6852
Belt .....	1021462		
<b>AHB6020</b>		2290	6829
Belt; W/29" Belt O.C. ....	1016174		6850
Belt; W/50" Belt O.C. ....	1036030		6860
Belt; W/60" Belt O.C. ....	1022460		7360
Gen. ....	1048684		
<b>MTD PRODUCTS, INC.</b>			
<b>Mower Attachments</b>			
<b>14A-999</b>			6604BR
Cross Deck .....	7540197		6841
P.T.O. ....	7540234		

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>138-803</b>			6501BR
Blade; W/44" Deck .....	7540293		6852
Deck .....	7540229		
<b>138-804</b>			6557BR
Deck; W/39" Deck .....	7540271		
<b>138-805</b>			6431BR
Belt .....	7540248		
<b>144-993; 145-993</b>			6604BR
Cross Deck .....	7540197		
<b>190-651</b>		3480	6948
Deck .....	7540113		
<b>190-761</b>			6428BR
Blade .....	7540125		
<b>190-762A</b>			7014BR
Deck .....	7540181		6510BR
Drive .....	7540180		
<b>190-765</b>		2530	6853
Blade .....	7540250		6809BR
Deck .....	7540251		
<b>190-765A</b>		2530	6853
Belt; W/38" Deck .....	7540250		6809BR
Belt; W/51" Belt O.C. ....	7540251		6850
Blade .....	7540214		
<b>190-794</b>			6949
Blade .....	7540328		
<b>190-795</b>			6639BR
Belt .....	7540264		
<b>190-798</b>			6853
Blade .....	7540250		6850
Deck .....	7540214		
<b>190-799</b>			6949
Blade .....	7540328		
<b>190-800</b>			6967
Blade .....	7540151		
<b>190-801</b>			6488BR
Blade .....	7540145		
<b>190-803</b>			6852
Blade; W/44" Deck; W/52" Belt O.C. ....	7540229		6501BR
Blade; W/44" Deck; W/74" Belt O.C. ....	7540293		
<b>190-804</b>			6557BR
Blade - Right .....	7540271		
<b>190-805</b>			6630BR
Blade; W/38" Deck .....	7540329		
<b>190-806</b>			6464BR
Belt; W/64" Belt O.C. ....	7540350		6637BR
Belt; W/79" Belt O.C. ....	7540349		
<b>190-823</b>			6428BR
Belt .....	7540125A		
<b>190-882A</b>			6604BR
Belt .....	7540197		
<b>190-931</b>			5716
Blade To Blade .....	7540260		6755BR
Eng. To Deck .....	7540230		
<b>190-935</b>			6755BR
Belt; W/56" Belt O.C. ....	7540230		6501BR
Belt; W/74" Belt O.C. ....	7540293		
<b>190-935A</b>			6755BR
Blade .....	7540230		6354
Deck .....	7540246		
<b>190-957A</b>			7014BR
Blade .....	7540181		6755BR
Drive .....	7540230		

Lawn & Garden Equipment

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>Mower Attachments - Continued</b>			
190-958; 190-958A Drive .....	7540230		6755BR
190-982; 190-982A Blade .....	7540125		6428BR
190-992; 190-992A Belt .....	7540197		6604BR
190-993 Cross Deck .....	7540197		6604BR
190-993A Belt .....	7540197		6604BR
191-651 Deck .....	7540113	3480	6948
191-761 Blade .....	7540125		6428BR
191-957A Blade .....	7540181		7014BR
Drive .....	7540230		6755BR
191-958A Drive .....	7540230		6755BR
191-982A Blade .....	7540125		6428BR
191-992A Belt .....	7540197		6604BR
192-651 Deck .....	7540113	3480	6948
192-761 Blade .....	7540125		6428BR
192-931; 192-935 Blade To Blade .....	7540260		5716
Eng. To Deck .....	7540230		6755BR
192-957 Blade .....	7540230		6755BR
Drive .....	7540181		7014BR
192-958 Blade .....	7540230		6755BR
Drive .....	7540215		6379
192-962; 192-982 Blade .....	7540125		6428BR
192-992; 192-993 Belt .....	7540197		6604BR
193-752 Blade .....	7540184		6852
Deck .....	7540180		6510BR
193-762; 193-762A Deck .....	7540181		7014BR
Drive .....	7540180		6510BR
193-962 Blade .....	7540125		6428BR
194-762; 194-762A Deck .....	7540181		7014BR
Drive .....	7540180		6510BR
194-765 Deck .....	7540250	2530	6853
Drive .....	7540251		6809BR
194-931 Blade To Blade .....	7540260		5716
Eng. To Deck .....	7540230		6755BR
194-935 Blade .....	7540230		6755BR
Deck .....	7540246		6354
194-957 Blade .....	7540181		7014BR
Drive .....	7540230		6755BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>Mower Attachments - Continued</b>			
194-958 Blade .....	7540230		6755BR
Drive .....	7540215		6379
194-962; 194-962A Blade .....	7540125		6428BR
194-992; 194-993 Belt .....	7540197		6604BR
195-746 Eng. To Spindle .....	7540229		6852
Spindle To Snow Thrower .....	7540283		6895
195-762; 195-762A Deck .....	7540181		7014BR
Drive .....	7540180		6510BR
195-765 Belt; W/51" Belt O.C. ....	7540251		6809BR
Belt; W/53" Belt O.C. ....	7540250	2530	6853
195-795; 195-796; 195-797 Belt .....	7540264		6639BR
195-798 Belt; W/62" Belt O.C. ....	7540198		6451BR
Blade .....	7540250		6853
Deck .....	7540214		6850
195-799 Blade .....	7540276		6848
195-800 Blade .....	7540151		6967
195-801 Blade .....	7540145		6488BR
195-802 Belt; W/36" Deck .....	7540277		6871
195-803 Belt; W/52" Belt O.C. ....	7540229		6852
Belt; W/74" Belt O.C. ....	7540293		6501BR
195-931 Blade To Blade .....	7540260		5716
Eng. To Deck .....	7540230		6755BR
195-935 Belt; W/56" Belt O.C. ....	7540230		6755BR
Belt; W/74" Belt O.C. ....	7540293		6501BR
195-942; 195-943 Belt .....	7540218		6959
195-957 Blade .....	7540181		7014BR
Drive .....	7540230		6755BR
195-958 Blade .....	7540230		6755BR
Drive .....	7540215		6379
195-962 Blade .....	7540125		6428BR
195-992 Belt .....	7540197		6604BR
195-993 Cross Deck .....	7540197		6604BR
196-651 Deck .....	7540113	3480	6948
196-762A Deck .....	7540181		7014BR
Drive .....	7540180		6510BR
196-765 Blade .....	7540250	2530	6853
Deck .....	7540251		6809BR
196-795; 196-796; 196-797 Belt .....	7540264		6639BR





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>196-798</b>			
Blade .....	7540250		6853
Deck .....	7540214		6850
<b>196-799</b>			
Belt; W/30" Deck; W/48 7/8" Belt O.C. ....	7540328		6949
Belt; W/30" Deck; W/53" Belt O.C. ....	7540250		6853
<b>196-800</b>			
Blade .....	7540151		6967
<b>196-801</b>			
Blade .....	7540145		6488BR
<b>196-802</b>			
Belt; W/36" Deck .....	7540277		6871
<b>196-803</b>			
Deck; W/52" Belt O.C. ....	7540229		6852
Deck; W/74" Belt O.C. ....	7540293		6501BR
<b>196-804</b>			
Deck; W/39" Deck .....	7540271		6557BR
<b>196-805; 196-806</b>			
Blade; W/38" Deck .....	7540329		6630BR
<b>196-931</b>			
Deck; W/44" Rear Discharge .....	7540230		6755BR
<b>196-935</b>			
Deck .....	7540230		6755BR
Eng. To Deck .....	7540293		6501BR
<b>196-962; 196-982A</b>			
Blade .....	7540125		6428BR
<b>196-993</b>			
Cross Deck .....	7540197		6604BR
<b>197-458A</b>			
Deck .....	7540213		6853
<b>197-651</b>		3480	6948
Deck .....	7540113		
<b>197-762A</b>			
Deck .....	7540181		7014BR
Drive .....	7540180		6510BR
<b>197-957A; 197-958A; 197-975A</b>			
Deck; W/105" Belt O.C. ....	7540125		6428BR
Deck; W/53" Belt O.C. ....	7540213		6853
<b>197-982A</b>			
Blade .....	7540125		6428BR
<b>197-992A</b>			
Belt .....	7540197		6604BR
<b>198-651</b>		3480	6948
Deck .....	7540113		
<b>198-761</b>			
Blade .....	7540125		6428BR
<b>198-762A</b>			
Deck .....	7540181		7014BR
Drive .....	7540180		6510BR
<b>198-957A</b>			
Blade .....	7540181		7014BR
Drive .....	7540230		6755BR
<b>198-958A</b>			
Drive .....	7540230		6755BR
<b>198-982A</b>			
Blade .....	7540125		6428BR
<b>198-992A</b>			
Belt .....	7540197		6604BR
<b>199-651</b>		3480	6948
Deck .....	7540113		
<b>199-761</b>			
Blade .....	7540125		6428BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>199-762A</b>			
Deck .....	7540181		7014BR
Drive .....	7540180		6510BR
<b>199-935A</b>			
Blade .....	7540230		6755BR
Deck .....	7540246		6354
<b>199-957; 199-957A</b>			
Blade .....	7540181		7014BR
Drive .....	7540230		6755BR
<b>199-958; 199-958A</b>			
Drive .....	7540230		6755BR
<b>199-982; 199-982A</b>			
Blade .....	7540125		6428BR
<b>199-992; 199-993</b>			
Belt .....	7540197		6604BR
<b>Snow Thrower Attachments</b>			
<b>180-469A; 180-486; 180-491; 190-469A; 190-486; 190-491</b>			
Auger; W/85" Belt O.C. ....	7540236		6885
Auger; W/89" Belt O.C. ....	7540294		6889
Drive; W/32" Belt O.C. ....	7540205		6673BR
Drive; W/49" Belt O.C. ....	7540185		6849
<b>190-496A</b>			
Auger .....	7540202		6885
Drive .....	7540185		6849
<b>190-658</b>			
Belt .....	6434		6951
<b>190-766A</b>			
Drive .....	7540253		6843
<b>190-768</b>			
Belt .....	6511		A66
<b>190-830</b>			
Eng. To Spindle .....	7540229		6852
<b>190-930</b>			
Belt; W/50" Belt O.C. ....	7540206		6850
Belt; W/88" Belt O.C. ....	7540291		6641BR
<b>190-930A</b>			
Auger; W/50" Belt O.C. ....	7540206		6850
Auger; W/85" Belt O.C. ....	7540236		6885
<b>191-469A</b>			
Auger .....	7540236		6885
J.S. ....	7540185		6849
<b>191-491</b>			
Drive .....	7540299		6849
<b>191-658</b>			
Belt .....	6434		6951
<b>191-759A</b>			
Auger .....	7540186		6882
J.S. ....	7540180		6510BR
<b>191-768</b>			
Belt .....	6511		A66
<b>191-930A</b>			
Auger; W/50" Belt O.C. ....	7540206		6850
Auger; W/85" Belt O.C. ....	7540236		6885
<b>192-469; 192-486</b>			
Auger .....	7540236		6885
J.S. ....	7540185		6849
<b>192-679</b>			
Belt; W/31" Belt O.C. ....	S610	3310	6931
Belt; W/67" Belt O.C. ....	8431		6967
<b>192-759</b>			
Auger .....	7540186		6882
J.S. ....	7540180		6510BR

Lawn & Garden Equipment

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
<b>192-768</b>		3310	
Belt; W/31" Belt O.C. ....	S610		6931
Belt; W/67" Belt O.C. ....	8431		6967
<b>192-930</b>			6850
Belt; W/50" Belt O.C. ....	7540206		
<b>192-967</b>			6892
Drive .....	7540238		
<b>194-468</b>			6885
Auger .....	7540236		
J.S. ....	7540185		6849
<b>194-469</b>			6885
Auger .....	7540202		
Drive .....	7540185		6849
<b>194-469A</b>			6882
Belt; W/36" Auger .....	7540186		
Belt; W/36" Drive .....	7540185		6849
<b>194-486</b>			6885
Auger .....	7540236		
J.S. ....	7540185		6849
<b>194-759</b>			6882
Belt; W/36" Auger .....	7540186		
<b>194-759A</b>			6882
Auger .....	7540186		
J.S. ....	7540180		6510BR
<b>194-930</b>			6885
Auger .....	7540236		
Drive .....	7540206		6850
<b>194-968A; 194-969A</b>		3310	
Belt; W/31" Belt O.C. ....	S610		6931
Belt; W/67" Belt O.C. ....	8431		6967
<b>195-469</b>			6885
Auger .....	7540202		
Drive .....	7540185		6849
<b>195-486</b>			6885
Auger .....	7540236		
J.S. ....	7540185		6849
<b>195-759</b>			6882
Auger .....	7540186		
J.S. ....	7540180		6510BR
<b>195-930</b>			6885
Lower Belt .....	7540236		
Upper Belt .....	7540206		6850
<b>195-967</b>			6892
Drive .....	7540238		
<b>196-486</b>			6885
Auger .....	7540236		
J.S. ....	7540185		6849
<b>196-491</b>			6849
Belt; W/49" Belt O.C. ....	7540299		
Belt; W/89" Belt O.C. ....	7540294		6889
<b>196-658</b>			6951
Belt .....	6434		
<b>196-759A</b>			6882
Auger .....	7540186		
J.S. ....	7540180		6510BR
<b>196-830</b>			A110
Belt; W/112" Belt O.C. ....	7540295B		
Belt; W/52" Belt O.C. ....	7540229		6852
<b>196-930</b>			6850
Belt; W/50" Belt O.C. ....	7540206		
Belt; W/88" Belt O.C. ....	7540291		6641BR
<b>197-469A</b>			6885
Auger .....	7540202		
Drive .....	7540185		6849

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MTD PRODUCTS, INC. - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
<b>197-759A</b>			6882
Auger .....	7540186		
J.S. ....	7540180		6510BR
<b>199-469A</b>			6885
Auger .....	7540202		
Drive .....	7540185		6849
<b>199-658</b>			6951
Belt .....	6434		
<b>199-768</b>			A66
Belt .....	6511		
<b>19471-8</b>			6846
Eng. To J.S. ....	23145		
<b>19766-0</b>			6843
Drive .....	7540253		
<b>Tiller Attachments</b>			
<b>190-746</b>			6852
Eng. To Spindle .....	7540229		
Spindle To Snow Thrower .....	7540283		6895
<b>190-766</b>			6843
Drive .....	7540253		
<b>190-960; 192-766</b>			6843
Belt .....	7540253		
<b>194-746</b>			6852
Eng. To Spindle .....	7540229		
Spindle To Snow Thrower .....	7540283		6895
<b>194-766; 195-766; 195-960</b>			6843
Belt .....	7540253		
<b>195-982</b>			6428BR
Belt .....	7540125		
<b>196-766</b>			6843
Belt .....	7540253		
<b>196-960</b>			6843
Drive .....	7540253		
<b>MURRAY</b>			
<b>Mower Attachments</b>			
<b>0-3600</b>			A57
Blade .....	23882		
Cross Deck .....			6844
<b>0-4200</b>			6862
Blade .....	23748		
Cross Deck .....	23749		6899
<b>2-4036</b>			6859
Blade .....	37X24		
Cross Deck .....	37X3		6846
<b>2-4042</b>			6451BR
Blade .....	37X40		
Cross Deck .....	37X22		6642BR
<b>8-3600</b>			A57
Blade .....	23796		
Cross Deck .....			6844
<b>8-4200</b>			6862
Blade .....	23748		
Cross Deck .....	23749		6899
<b>9-3600</b>			A57
Blade .....	23882		
Cross Deck .....			6844
<b>9-4200</b>			6862
Blade .....	23748		
Cross Deck .....	23749		6899
<b>81-36000</b>			6449BR
Blade; W/55" Belt O.C. ....	37X12		
Blade; W/59" Belt O.C. ....	37X24		6859
Cross Deck .....	37X3		6846



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>MURRAY - Continued</b>			
<b>Mower Attachments - Continued</b>			
82-13450 Drive; W/Rear Mount Tiller .....	37X32		6845
82-24036 Blade .....	37X24		6859
Cross Deck .....	37X3		6846
83-24042 Blade; W/62" Belt O.C. ....	37X21		6451BR
Blade; W/64" Belt O.C. ....	37X40		6451BR
Cross Deck .....	37X22		6642BR
84-24042 Blade; W/11 H.P. Tractor .....	37X21		6451BR
Blade; W/16, 18 H.P. Tractor .....	37X40		6451BR
Cross Deck .....	37X22		6642BR
85-36508 Blade .....	37X43		6601BR
Transaxle .....	37X45		6490BR
85-36508X4 Blade .....	37X43		6601BR
Transaxle .....	37X55		6891
3600 Blade .....	23882		A57
Cross Deck .....	37X3		6846
Drive .....	23796		A57
4200 Cross Deck .....	23749		6899
<b>Snow Thrower Attachments</b>			
5-24570 Belt; W/58" Belt O.C. ....	12903		6858
Belt; W/91" Belt O.C. ....	11904		6891
6-24550 Belt; W/43" Belt O.C. ....	11483		6943
Belt; W/76" Belt O.C. ....			6876
6-24570; 7-24570; 8-24570 Belt; W/58" Belt O.C. ....	12903		6858
Belt; W/91" Belt O.C. ....	11904		6891
9-24576 Eng. To Auger .....	11904		6891
<b>Tiller Attachments</b>			
4-10030 Blade .....	37X46		6827
5-13450; 6-13450; 7-13450; 8-13450; 81-13360 Belt .....	37X32		6845
<b>NOMA</b>			
<b>Mower Attachments</b>			
13442 Blade; W/36" Rear Discharge; W/82" Belt O.C. ....	48044		6454BR
Blade; W/36" Rear Discharge; W/84" Belt O.C. ....	49878		6467BR
13443 Blade; W/36" Side Discharge .....			6971
<b>PANZER</b>			
<b>Generator Attachments</b>			
16AC1 Belt; For Model T65 .....	74211	2270	6827
Belt; For Models T70, T70B, T70BES, T75, T758 .....	16AC17	2260	6826
<b>P.T.O. Kits</b>			
51PT Belt .....	51PT4	3350	6935
52PT; 53PT; 54PT; 55PT Belt .....	74223	3330	6933

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>PANZER - Continued</b>			
<b>Saw Attachments</b>			
15AC1 Belt .....	15AC19	3710	6971
<b>Snow Thrower Attachments</b>			
17AC1; 17AC2 Belt; W/44" Belt O.C. ....	74218	3440	6944
Belt; W/48" Belt O.C. ....	3312	3480	6948
Spout .....	17AC253	1420	6742
<b>Sprayer Attachments</b>			
12AC1 Belt .....		2610	6861
<b>Spreader Attachments</b>			
PS1 Belt .....	PS14	2580	6858
<b>Tiller Attachments</b>			
9AC3; 9AC4 Belt .....	74209		6860
9AC5 Belt .....	3302		6824
9AC6 Belt .....	74224		6840
9AC7 Belt; W/33" Belt O.C.; W/1/2" Belt T.W. ....	74203		6833
Belt; W/33" Belt O.C.; W/5/8" Belt T.W. ....	74223		6933
11AC7 Belt .....	11AC71		6925
11AC8 Belt .....	11AC886		6867
11AC9; 11AC9B Belt; W/35" Belt O.C. ....	11AC936		6935
Belt; W/36" Belt O.C. ....	11AC936A		6936
Belt; W/37" Belt O.C. ....			6937
13AC; 13AC2 Belt .....	13AC143		6932
17AC2A Belt .....	74206		6949
<b>PENNEYS</b>			
<b>Mower Attachments</b>			
3389 Blade .....	7540181		7014BR
Eng. To Deck .....	7540180		6510BR
3390 Cross Deck .....			6846
3391 Blade .....	23882		A57
Cross Deck .....			6846
3397 Deck .....	7540125		6428BR
3398 Deck .....	7540197		6604BR
<b>Tiller Attachments</b>			
Tillers Belt; W/96" Belt O.C. ....	105340		6996
<b>POWER KING</b>			
<b>Hyd. Pump Attachments</b>			
Side Mounted Pump Belt; 1974 & Older .....	810000		6831
Top Mounted Pump Belt; 1975 & Newer .....	810025		6825

Lawn & Garden Equipment

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>POWER KING - Continued</b>			
<b>Log Splitter Attachments</b>			
Logsplitters			
Belt .....	810037		6837
<b>Mower Attachments</b>			
<b>36" Deck</b>			
Cross Deck .....	810036		6836
<b>42" Deck</b>			
Traction; 1982 & Newer .....	810064		6864
<b>48" Deck</b>			
Cross Deck; 1980 & Newer .....	810094		6894
Drive .....	810036		6836
<b>P.T.O. Attachments</b>			
<b>Mainline</b>			
Belt .....	810066		6866
<b>Snow Thrower Attachments</b>			
<b>42" Snow Thrower</b>			
Eng. To Hitch; 1980 .....	810070		6870
Eng. To Hitch; 1981 & Newer .....	810074		6874
Hitch To Header; 1980 .....			6867
Hitch To Header; 1981 & Newer .....	810070		6870
<b>48"</b>			
Belt; 1976-1971 .....	810094		6894
Belt; 1977 .....	810064		6864
Belt; 1978 & Newer .....	810048		6848
<b>Sprayer Attachments</b>			
<b>35"</b>			
Belt .....	810000		6831
<b>REO</b>			
<b>Mower Attachments</b>			
<b>Rotary Mower</b>			
Belt; W/42" Belt O.C. ....	18076	2420	6842
Belt; W/45" Belt O.C. ....	18121	2450	6845
<b>ROPER</b>			
<b>Mower Attachments</b>			
<b>38" Rotary; 40" Rotary</b>			
Deck .....	1563R		6950
<b>42" Rotary</b>			
Deck .....	3716R		6887
<b>48" Rotary</b>			
Deck .....	3717R		6892
Drive - Eng. To Center Mandrel .....	6941R		BX100
<b>Shredder Attachments</b>			
<b>TT6531RO</b>			
Belt .....	3541R		6971
<b>TT6631RO</b>			
Eng. To Shredder .....	2630R		6968
<b>Sicklebar Attachments</b>			
<b>TT2631RO</b>			
Eng. To Flywheel .....	5308H		6565
<b>Snow Thrower Attachments</b>			
<b>LA049AR</b>			
Drive .....			6977
<b>TT679AR</b>			
Belt .....	10830		6860
<b>TT6231RO</b>			
Belt .....	1835R		6956
<b>Tiller Attachments</b>			
<b>TT508AR; TT508BR; TT508CR</b>			
Eng. To Tine .....	634A563		②6837
<b>TT518AR</b>			
Eng. To Tine .....	8225R		6837

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>ROPER - Continued</b>			
<b>Tiller Attachments - Continued</b>			
<b>TT5031R; TT5031R1; TT5051R1; TT5051R2; TT5051RO</b>			
Eng. To Tine .....	634A563		②6837
<b>ROTO-HOE</b>			
<b>Cutter Attachments</b>			
<b>3200-7</b>			
Belt; For Model 700EC .....	3048	2570	6857
<b>Saw Attachments</b>			
<b>Brush Saw</b>			
Belt; For Model 300CD .....		2430	6843
<b>Saw Buck</b>			
Belt; For Model 300CD .....		2510	6851
<b>Shredder Attachments</b>			
<b>502H; 552H</b>			
Belt; For Model 700EC .....	107	2660	6866
<b>Sicklebar Attachments</b>			
<b>SL30; SL36</b>			
Drive .....	4032A		6843
<b>Snow Thrower Attachments</b>			
<b>969</b>			
Drive .....			6837
<b>Tiller Attachments</b>			
<b>220IL; 229TC</b>			
Belt .....			6843
<b>700CD</b>			
Fast Speed Drive; For Model 700EC .....			6849
Slow Speed Drive; For Model 700EC .....	1088		6854
<b>910RB; 910RS</b>			
Belt .....	1542B		6961
<b>990RB; 990RS</b>			
Belt .....	1542C		6960
<b>ROTOTILLER</b>			
<b>Tiller Attachments</b>			
<b>Gen.</b>			
Belt .....			6833
<b>Reel Mower</b>			
Belt .....			6838
<b>Rotary Mower</b>			
Belt; W/32" Belt O.C. ....			6832
Belt; W/45" Belt O.C. ....			6845
<b>SCAG POWER EQUIPMENT, INC.</b>			
<b>Mower Attachments</b>			
<b>SLM-40; SLM-40T; SLM-40W</b>			
Deck Drive .....	48086		6858BR
<b>SLM-48; SLM-48T; SLM-48W</b>			
Blade - Right .....	48087		6864BR
Deck Drive .....	48088		6904BR
<b>SLM-52</b>			
Blade - Right .....	48285		7040BR
<b>SM-48</b>			
Deck Drive .....	48081		6815BR
<b>SM-52</b>			
Blade - Right .....	48285		7040BR
Deck Drive .....	48530		6492BR
<b>SM-61</b>			
Blade - Right .....	48084		6622BR
Deck Drive .....	48083		6645BR
<b>SM-61A</b>			
Deck Drive .....	48912		6688BR

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SCAG POWER EQUIPMENT, INC. - Continued</b>				<b>SCOTTS - Continued</b>			
<b>Mower Attachments - Continued</b>				<b>Tiller Attachments</b>			
<b>SM-72</b>				<b>MP5983</b>			
Deck Drive .....	48359		6994	Front Drive .....	M112006		6793BR
<b>SM-72A</b>				Rear Drive .....	M137547		A103
Blade - Right .....	48295		B68	<b>SEARS ROEBUCK</b>			
<b>SMST-72A</b>				<b>Composter Attachments</b>			
Deck Drive .....	481980		6741BR	<b>917.253390</b>			
<b>SMT-52A</b>				Belt .....	6118R	3760	6976
Deck Drive .....	482281		6574BR	<b>917.253430</b>			
<b>SMT-61A</b>				Belt .....	6944R	3710	6971
Deck Drive .....	481558		6566BR	<b>917.253470</b>			
<b>SMT-40</b>				Belt .....	5655R	3680	6968
Blade - Right .....	482091		6683BR	<b>917.253480</b>			
<b>SMT-48A</b>				Belt .....	4965R	3640	6964
Deck Drive .....	482138		6563BR	<b>Mower Attachments</b>			
<b>SMT-52A</b>				<b>502.251340; 502.251360</b>			
Deck Drive .....	482140		6564BR	Blade .....			6846
<b>SMTZ-61</b>				Eng. To Deck .....	21649		6449BR
Deck Drive .....	48752		6574BR	<b>502.251370</b>			
<b>SMWC-61A</b>				Blade .....	23223		6895
Deck Drive .....	482652		6720BR	Eng. To Deck .....	23214		6859
<b>SMZ-48</b>				<b>502.253610</b>			
Blade - Right .....	48087		6864BR	Blade .....			6846
Deck Drive .....	48799		6665BR	Deck .....	23796		A57
<b>SMZ-52</b>				<b>502.253620; 502.253621; 502.253622</b>			
Blade - Right .....	48285		7040BR	Blade .....	23749		6899
Deck Drive .....	481001		6568BR	Deck .....	23748		6862
<b>SMZ-61</b>				<b>502.253623</b>			
Deck Drive .....	48996		6785BR	Blade .....	37X22		6642BR
<b>SWM-32</b>				Deck .....	37X21		6451BR
Deck Drive .....	48278		6979	<b>917.60042</b>			
<b>SWM-36</b>				Blade .....	4833H		6841
Deck Drive .....	48204		6573BR	Drive .....	4832H		6898
<b>SWM-48</b>				<b>917.60606; 917.60620</b>			
Blade - Right .....	48087		6864BR	Belt; W/48" Belt O.C. ....		3480	6948
Deck Drive .....	48089		6701BR	Belt; W/49" Belt O.C. ....		3490	6949
<b>SWM-52; SWM-52A</b>				<b>917.60635; 917.60642; 917.60651</b>			
Blade - Right .....	48285		7040BR	Blade .....	4833H		6841
Deck Drive .....	48286		6703BR	Drive .....	4832H		6898
<b>SWM-61</b>				<b>917.60655; 917.60655A</b>			
Deck Drive .....	48264		B98	Blade .....	4833H	2410	6841
<b>SWM-61A</b>				Deck .....	6517H		69100
Deck Drive .....	48088		6904BR	Drive .....	4832H		6898
<b>SWM-72</b>				<b>917.62606</b>			
Blade - Right .....	48295		B68	Blade .....	5600H		6948
Deck Drive .....	48296		6615BR	<b>917.99550</b>			
<b>SWMU-52A</b>				Deck .....	5600H		6948
Blade - Right .....	48285		7040BR	<b>917.99620</b>			
Deck Drive .....	481922		6806BR	Blade .....	5600H		6948
<b>SWMU-61A</b>				<b>917.122217X</b>			
Blade - Right .....	48286		6703BR	Deck .....	106085X		6672BR
<b>SCOTTS</b>				<b>917.140475</b>			
<b>Grass Catcher Attachments</b>				Deck .....	140067		6551BR
<b>MP18374; MP18375</b>				<b>917.250090</b>			
Drive .....	H86061		6876	Blade .....	5600H		6948
<b>Snow Thrower Attachments</b>				<b>917.250110</b>			
<b>MP19540</b>				Blade .....	9495H		6887
Auger .....	M125661		3VX425	Drive .....	8718H	3490	6949
Drive .....	M131766		A120	<b>917.250119</b>			
				Deck .....	9517H		6949
				<b>917.250120</b>			
				Blade .....	5600H		6948

Lawn & Garden Equipment

LAWN ATTACHMENTS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>Mower Attachments - Continued</b>			
917.250121 Deck .....	9517H		6949
917.250122 Blade .....	9495H		6887
Drive .....	8718H	3490	6949
917.250123; 917.250129 Deck .....	9517H		6949
917.250520 Blade .....	1563R		6950
917.251010; 917.251011; 917.251012 Blade .....	3541R		6971
917.251020; 917.251021; 917.251030; 917.251040 Blade .....	4833H	2410	6841
Deck .....	6517H		69100
917.251042 Blade .....	7335H		6845
Main Drive .....	6517H		69100
917.251050 Blade .....	4833H	2410	6841
Deck .....	6517H		69100
917.251450 Gen.; W/Electric Start .....	5436H	7320	3V315
Starter/Gen.; W/Electric Start .....	3754H1		
917.252010; 917.252020; 917.252030; 917.252031; 917.252032; 917.252040 Blade .....	1563R		6950
917.253150; 917.253151 Blade .....	9495H		6887
Main Drive .....	6517H		69100
917.253160 Blade .....	9496H		6892
917.253161 Blade .....	6943R		6892
Deck .....	6517H		69100
917.253230 Blade .....	9495H		6887
Main Drive .....	6517H		69100
917.253240 Blade .....	6943R		6892
Deck .....	6517H		69100
917.253250 Blade .....	3716R		6887
917.253260 Blade .....	6943R		6892
917.253370 Blade .....	6942R		6887
917.253380 Blade .....	6943R		6892
917.253520 Blade .....	518J		6869
917.253521 Drive .....	100717N		6869
917.253530 Blade .....	6942R		6887
Deck .....	9121R		A112
917.253540; 917.253541 Blade .....	6942R		6887
Mower Drive .....	6941R		BX100
917.253550; 917.253551 Blade .....	6943R		6892
917.253560 Drive .....	100670N		6879

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>Mower Attachments - Continued</b>			
917.253570; 917.253571 Blade .....	6942R		6887
Deck .....	9121R		A112
917.253580; 917.253581 Blade .....	6942R		6887
Mower Drive .....	6941R		BX100
917.253582 Blade .....	6942R		6887
917.253590; 917.253591 Blade .....	6943R		6892
Mower Drive .....	6941R		BX100
917.253620 Blade .....	518J		6869
917.253630 Blade .....	6942R		6887
Mower Drive .....	6941R		BX100
917.253642; 917.253643; 917.253644; 917.253645; 917.253646 Blade .....	6943R		6892
Deck .....	5559J		6894
917.253650; 917.253651; 917.253652 Blade .....	6943R		6892
Deck .....	3704J		69100
917.253661 Deck .....	3704J		69100
917.253810; 917.253820 Cross Deck .....	106085X		6672BR
Deck .....	106085X		6672BR
Drive .....	106085X		6672BR
917.253830 Drive .....	106863X		6457BR
917.253840 Drive .....	106085X		6672BR
917.253991 Primary .....	110884X		6714BR
Secondary .....	106381X		6892
917.353590; 917.353591 Blade .....	6943R		6892
917.575123 Drive .....	758H		6857
917.575124 Drive .....	805H		6855
917.608100; 917.608150; 917.608200; 917.608500 Mower Drive .....	2692R		6983
917.643540; 917.643541; 917.643550; 917.643551 Drive .....	6941R		BX100
9171.253572 Deck .....	9121R		A112
<b>Saw Attachments</b>			
917.58016; 917.58061 Belt .....	7449M		6869
<b>Sicklebar Attachments</b>			
917.57569 Drive .....	4322M		6840
917.60639; 917.60656; 917.251520; 917.253120 Drive .....	5308H		6565
<b>Snow Blower Attachments</b>			
917.250662 Drive .....	1836R		6955





Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>				<b>SEARS ROEBUCK - Continued</b>			
<b>Snow Thrower Attachments</b>				<b>Snow Thrower Attachments - Continued</b>			
131.80371; 131.80372				842.240731			
Drive ..... 66114			6957	Belt; W/58" Belt O.C. .... 12903			6858
131.80379				Belt; W/91" Belt O.C. .... 11904			6891
Auger ..... 66114			6957	842.260011			
131.81170; 131.81171				Auger ..... 10242			6877
Drive ..... 62411			6936	Drive ..... 10241			6942
486.24839; 486.248391; 486.248400				842.260031; 842.260032			
Drive ..... 46989			6855	Drive ..... 9684			6996
486.248460				842.260041; 842.260061; 842.260063			
Drive ..... 46960			6940	Belt; W/78" Belt O.C. .... 11296			6878
536.24380				842.260071; 842.260072; 842.260073			
Belt; W/6" Dia. Pulley ..... 50931			6853	Belt ..... 10830			6860
Belt; W/80" Belt O.C. .... 308701			6980	842.260261			
842.24062				Auger ..... 11905			A49
Drive; W/43" Belt O.C. .... 11483			6943	842.260262			
Drive; W/78" Belt O.C. .... 11296			6878	Belt; W/51" Belt O.C. .... 11905			A49
842.24071				Belt; W/91" Belt O.C. .... 11904			6891
Drive; W/35" Belt O.C. .... 13394			6935	842.260621			
Drive; W/85" Belt O.C. .... 13376			6985	Belt; W/35" Belt O.C. .... 13394			6935
842.24073				Belt; W/85" Belt O.C. .... 13376			6985
Belt; W/58" Belt O.C. .... 12903			6858	842.260622			
Belt; W/91" Belt O.C. .... 11904			6891	Drive; W/35" Belt O.C. .... 13394			6935
842.24075				Drive; W/85" Belt O.C. .... 13376			6985
Drive; W/43" Belt O.C. .... 10371			6843	917.57575			
Drive; W/77" Belt O.C. .... 16297			6977	Drive ..... 4322M			6840
842.24077				917.57587			
Drive ..... 11483			6943	Drive ..... 9787M			6843
842.26003				917.60660			
Drive ..... 9684			6996	Belt; W/57" Belt O.C. .... 5859H			6957
842.26004; 842.26006				P.T.O.; W/29" Belt O.C. .... 3568H			6929
Belt; W/78" Belt O.C. .... 11296			6878	917.62615			
842.26007				Eng. .... 5357H	3530		6953
Belt ..... 10830			6860	Transaxle ..... 5559H	3800		6980
842.26008				917.80370			
Belt; W/43" Belt O.C. .... 11483			6943	Drive ..... 4703H			6948
Belt; W/76" Belt O.C. ....			6876	917.80378			
842.26009				Auger ..... 4703H			6948
Belt; W/76" Belt O.C. ....			6876	917.80470			
842.26026				Eng. .... 5357H	3530		6953
Auger ..... 11905			A49	Transaxle ..... 5559H	3800		6980
842.26027				917.99320			
Drive ..... 6876			6876	Auger ..... 5859H			6957
842.26061				917.250161			
Belt; W/43" Belt O.C. .... 11483			6943	Drive ..... 5357H	3530		6953
Belt; W/78" Belt O.C. .... 11296			6878	917.250530; 917.250540; 917.250650;			
842.26062				917.250660; 917.250661			
Belt; W/35" Belt O.C. .... 13394			6935	Drive ..... 1836R			6955
Belt; W/85" Belt O.C. .... 13376			6985	917.250680; 917.250681			
842.240621				Drive ..... 1835R			6956
Drive; W/43" Belt O.C. .... 11483			6943	917.251350; 917.251351; 917.251820			
Drive; W/78" Belt O.C. .... 11296			6878	Belt ..... 5859H			6957
842.240681				917.252493			
Drive; W/58" Belt O.C. .... 12903			6858	Drive ..... 8225R			6837
Drive; W/91" Belt O.C. .... 11904			6891	917.252620			
842.240711; 842.240712				Drive ..... 5357H	3530		6953
Auger ..... 13394			6935	917.253220			
842.240713				Drive ..... 5859H			6957
Drive; W/35" Belt O.C. .... 13394			6935	917.253320; 917.253350			
Drive; W/85" Belt O.C. .... 13376			6985	Belt ..... 5859H			6957
842.240721; 842.240722; 842.240723;				917.803750			
842.240724; 842.240725; 842.240726;				Auger ..... 4703H			6948
842.240729							
Drive ..... 11483			6943				

Lawn & Garden Equipment

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SEARS ROEBUCK - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
917.804750			
Eng. To Gear Box .....	5357H	3530	6953
Eng. To Trans. ....	5559H	3800	6980
<b>Tiller Attachments</b>			
917.62403; 917.62404; 917.98350; 917.251840			
Drive .....	4897H		6837
917.251860			
Drive .....	8225R		6837
917.251880; 917.251882; 917.251883; 917.251884; 917.251890; 917.251891			
Drive .....	634A563		②6837
917.252370			
Drive .....	8225R		6837
917.252460			
Secondary .....	104022X		6843
917.252490; 917.252491; 917.252492			
Drive .....	8225R		6837
917.TA157AR; 917.TA157BR; 917.TA188AR; 917.TT508CR; 917.TX220AR			
Tine .....	634A563		6837
<b>Weed Cutter Attachments</b>			
917.575125			
Drive .....	758H		6857
917.575126			
Drive .....	805H		6855
<b>SHAW</b>			
<b>Hyd. Lift Attachments</b>			
<b>Hyd. Lifts</b>			
Drive .....	S3855	1330	6733
<b>Mower Attachments</b>			
<b>M50</b>			
Belt .....	S3022		3V400
<b>Trail Mower</b>			
Drive .....	S3541		3V500
<b>P.T.O. Kits</b>			
<b>Front Mounted</b>			
Drive .....	S4763		6935
<b>Sicklebar Attachments</b>			
<b>D4-10</b>			
Primary .....	S3299		6840
Secondary .....	S3300		6845
<b>HD12</b>			
Primary .....	S3304		6848
Secondary .....	S3300		6845
<b>Snow Thrower Attachments</b>			
<b>ST320</b>			
Primary .....	S3299		6840
Secondary .....	S3304		6848
<b>ST330</b>			
Belt .....	S3472		6867
<b>ST348</b>			
Primary .....	S3299		6840
<b>SIMPLICITY</b>			
<b>Alternator Attachments</b>			
<b>1690558</b>			
Belt; W/5000 Watt Alt. ....			6878
<b>Blower Attachments</b>			
<b>Deck Blower</b>			
Belt; W/42", 46" Deck .....	1705563		6874

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>Blower Attachments - Continued</b>			
<b>Turbo Collector</b>			
Turbo Drive; W/32" Belt O.C. ....	1700415		6732
Turbo Drive; W/39" Belt O.C. ....	1679915		6739
<b>Generator Attachments</b>			
<b>170</b>			
Drive .....	122060		6736
<b>220</b>			
Drive; W/52" Belt O.C. ....	122069		6853
Drive; W/53" Belt O.C. ....			6853
<b>Grass Catcher Attachments</b>			
<b>1691854</b>			
Drive .....	1711901		6835
<b>Lawn Revitalizer Attachments</b>			
<b>629</b>			
Drive .....	108248		6848
<b>688</b>			
Drive .....	105340		6996
<b>931; 1600342</b>			
Drive .....	174364		6849
<b>1690079</b>			
Drive .....	105340		6996
<b>Mower Attachments</b>			
<b>087</b>			
Drive .....	174911		6844
<b>117</b>			
Drive .....	109061		6828
<b>122</b>			
Drive .....	174911		6844
<b>153</b>			
Drive .....	108175		6856
Spindle .....	156120		6863
<b>183</b>			
Drive .....	109061		6828
<b>190</b>			
Cross Deck .....	174911		6844
Spindle .....	108209		6415BR
<b>207</b>			
Cross Deck .....	108248		6848
Spindle .....	156120		6863
<b>236</b>			
Drive .....	174911		6844
<b>285</b>			
Cross Deck .....	108099		6844
Spindle .....	108209		6415BR
<b>289</b>			
Drive .....	106723		6879
Spindle .....	108151		6863
<b>333</b>			
Spindle .....	156120		6863
<b>358</b>			
Drive .....	108407		6847
<b>407</b>			
Cross Deck .....	174911		6844
Spindle .....	108209		6415BR
<b>414</b>			
Cross Deck .....	108458		6845
Spindle .....			6885
<b>417</b>			
Drive .....	176439		6424BR
Spindle .....	108151		6863
<b>422</b>			
Spindle .....	108505		6870

②Two Required



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>501</b>			
Cross Deck .....	174911		6844
Spindle .....	108209		6415BR
<b>502</b>			
Cross Deck .....	108458		6845
Spindle .....			6885
<b>541</b>			
Drive .....	108248		6848
<b>544</b>			
Cross Deck .....	108248		6848
Spindle .....	108209		6415BR
<b>557</b>			
Drive .....	170164		A75
<b>576; 669</b>			
Spindle .....	165048		6775BR
<b>740</b>			
Spindle .....			6885
<b>784</b>			
P.T.O. ....	176439		6424BR
Spindle .....	108209		6415BR
<b>844</b>			
Spindle .....	108505		6870
<b>847</b>			
Drive .....	174911		6844
<b>883</b>			
Drive .....	174687		6873
Spindle .....	108151		6863
<b>885</b>			
P.T.O. ....	176439		6424BR
Spindle .....	108209		6415BR
<b>886</b>			
Spindle .....			6885
<b>926</b>			
Drive .....	174911		6844
<b>1540</b>			
Belt .....	1668065		6869
<b>8788</b>			
Drive .....	108505		6870
<b>1600416</b>			
Drive .....	174364		6849
<b>1690021</b>			
Spindle .....	165048		6775BR
<b>1690022</b>			
Belt .....	108209		6415BR
<b>1690023</b>			
Spindle .....	108505		6870
<b>1690074</b>			
Drive .....	172420		A91
<b>1690082</b>			
P.T.O. ....	176439		6424BR
Spindle .....	108209		6415BR
<b>1690083</b>			
Belt .....	108209		6415BR
<b>1690189; 1690205</b>			
Drive .....	108505		6870
<b>1690210</b>			
Spindle .....	108209		6415BR
<b>1690252</b>			
P.T.O. ....	176439		6424BR
Spindle .....	108209		6415BR
<b>1690269</b>			
Drive .....	108505		6870

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>1690271</b>			
P.T.O. ....	176439		6424BR
Spindle .....	1656960		6811BR
<b>1690273</b>			
Spindle .....	108209		6415BR
<b>1690274</b>			
Drive .....	108505		6870
<b>1690375</b>			
P.T.O. ....	1664644		6378
<b>1690412</b>			
Drive .....	1668066		6481BR
<b>1690413</b>			
Drive .....	1665638		6560
<b>1690501</b>			
P.T.O. ....	1666801		6640BR
Spindle .....	1656960		6811BR
<b>1690529</b>			
Drive .....	1664946		6857
<b>1690530</b>			
Drive .....	1665024		6854
<b>1690575</b>			
Spindle .....	108209		6415BR
<b>1690627</b>			
Arbor; W/36" Rotary Mower .....	1707740		6869
<b>1690670</b>			
Spindle .....	108209		6415BR
<b>1690708</b>			
Belt; W/42" Deck .....	1668066		6481BR
Belt; W/44" Deck .....	167031		6578BR
P.T.O. Deck .....	1601672		6799BR
<b>1690709</b>			
Drive .....	1665638		6560
<b>1690710</b>			
Arbor; W/36" Rotary Mower .....	1707740		6869
<b>1690769</b>			
P.T.O. ....	1671076		6765BR
<b>1690838</b>			
Drive .....	108505		6870
<b>1690839</b>			
Arbor; W/36" Rotary Mower .....	1707740		6869
<b>1690891</b>			
Mower Drive .....	1713515		6458BR
<b>1690892</b>			
P.T.O. ....	1673667		6895
<b>1691218</b>			
Arbor .....	1656960		6811BR
P.T.O. ....	1666801		6640BR
<b>1691219</b>			
Arbor .....	1657044		6521BR
P.T.O. ....	1713515		6458BR
<b>1691260</b>			
Drive .....	1700415		6732
<b>1691332</b>			
Spindle .....	1664644		6378
<b>1691356</b>			
Turbo Drive .....	1679915		6739
<b>1691419</b>			
Arbor .....	1713549		6478BR
<b>1691423</b>			
Arbor .....	1668066		6481BR

Lawn & Garden Equipment

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>1691425</b>			
Arbor .....	1703466		6484BR
Deck .....	1665638		6560
<b>1691437</b>			
Mower .....	1665024		6854
<b>1691606</b>			
Turbo Drive .....	1679914		6749
<b>1691607</b>			
Turbo Drive .....	1679913		6745
<b>1691662</b>			
Deck Drive; 1997-1993 .....	1703371		6708BR
<b>1691704</b>			
Arbor .....	1716854		6643BR
<b>1691705</b>			
Arbor .....	1721532		6798BR
P.T.O. ....	1601672		6799BR
<b>1691736</b>			
Arbor .....	1703466		6484BR
<b>1691810</b>			
Drive .....	1700415		6732
<b>1691847</b>			
Arbor .....	1712481		6860
Drive .....	1712482		6878
<b>1691849</b>			
Arbor .....	1712937		AX110
Drive .....	1712595		BX108
<b>1691850</b>			
Arbor .....	1712596		AX120
Drive .....	1712595		BX108
<b>1691867</b>			
Turbo Drive .....	1705141		6747
<b>1691868</b>			
Turbo Drive .....	1705142		6738
<b>1691993</b>			
Mower Drive .....	1665024		6854
<b>1691996</b>			
Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
<b>1691998</b>			
Drive .....	1700415		6732
<b>1692003</b>			
Turbo Drive .....	1679914		6749
<b>1692004</b>			
Turbo Drive .....	1679915		6739
<b>1692026</b>			
Arbor .....	1721532		6798BR
P.T.O. ....	1601672		6799BR
<b>1692030</b>			
Drive .....	1707956		6739
<b>1692126; 1692127</b>			
Drive .....	1719746		6873
<b>1692128</b>			
Drive .....	1719819		6434BR
<b>1692257</b>			
Turbo Drive .....	1679914		6749
<b>1692358</b>			
Arbor .....	1716854		6643BR
<b>1692366</b>			
Arbor .....	1713549		6478BR
<b>1692543</b>			
Drive .....	1719746		6873

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>1692545</b>			
Drive .....	1719819		6434BR
<b>1692626</b>			
Turbo Drive .....	1705141		6747
<b>1692682</b>			
Arbor .....	1716854		6643BR
<b>1692684; 1692686</b>			
Arbor .....	1721532		6798BR
P.T.O. ....	1601672		6799BR
<b>1692688</b>			
Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
<b>1692714</b>			
Turbo Drive .....	1705141		6747
<b>1692715</b>			
Turbo Drive .....	1705142		6738
<b>1692716</b>			
Turbo Drive .....	1707956		6739
<b>1692744</b>			
Arbor .....	1718017		6684BR
<b>1692858</b>			
Drive .....	1717146		6736
<b>1692881</b>			
Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
<b>1692890</b>			
Arbor .....	1657044		6521BR
P.T.O. ....	1713515		6458BR
<b>1692912</b>			
Arbor .....	1719819		6434BR
<b>1692914</b>			
Arbor .....	1713549		6478BR
<b>1692936</b>			
Turbo Drive .....	1679914		6749
<b>1692937</b>			
Turbo Drive .....	1679915		6739
<b>1693078</b>			
Arbor .....	1716854		6643BR
<b>1693106</b>			
Drive .....	1717146		6736
<b>1693188</b>			
Arbor .....	1718017		6684BR
<b>1693225; 1693226</b>			
Turbo Drive .....	1705141		6747
<b>1693227</b>			
Turbo Drive .....	1705142		6738
<b>1693228</b>			
Turbo Drive .....	1707956		6739
<b>1693235</b>			
Arbor .....	1703836		6524BR
P.T.O. ....	1719746		6873
<b>1693267</b>			
Arbor .....	1703836		6524BR
P.T.O. ....	1707740		6869
<b>1693418</b>			
Arbor .....	1657044		6521BR
P.T.O. ....	1713515		6458BR
<b>1693464</b>			
Arbor .....	1716854		6643BR
<b>1693527</b>			
Arbor .....	1719911		68117



Application	OEM No.	Standard Belt No.	Premium Belt No.	Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>				<b>SIMPLICITY - Continued</b>			
<b>Mower Attachments - Continued</b>				<b>Sicklebar Attachments - Continued</b>			
1693552 Arbor .....	1716854		6643BR	623; 687 Drive .....	101137		A66
1693553 Arbor .....	1718017		6684BR	707 Knife Drive .....	173948		6857
1693554 Arbor .....	1721532		6798BR	785 Drive .....	174911		6844
1693585 Arbor .....	1721533		6856	Knife Drive .....	174224		6866
1693629 Arbor .....	1671076		6765BR	1600197 Knife Drive .....	173948		6857
P.T.O. ....	1722039		6525BR	1690030 Drive .....	174911		6844
1693706 Turbo Drive .....	1720932		6737	Knife Drive .....	174224		6866
1693792 Arbor .....	1716854		6643BR	<b>Snow Thrower Attachments</b>			
1693795 Arbor .....	1718017		6684BR	293 Drive .....	106723		6879
1693825 Arbor .....	1719819		6434BR	311 Pulley; W/35" Belt O.C. ....	121078		6835
1693827 Arbor .....	1713549		6478BR	Pulley; W/45" Belt O.C. ....	152017		B42
Reel 20" Drive; For Walking Tractor .....	174883		6834	345 Drive .....	106769		A54
Reel 24" Drive; For Walking Tractor .....	1665706		6839	419 Drive .....	106723		6879
Reel 30" Drive; For Walking Tractor .....	1664457		6841	421 Drive .....	106769		A54
Rotary 20" Cross Deck; For Walking Tractor .....	176917		6837	476 Drive .....			6878
Drive; W/31" Belt O.C.; For Walking Tractor .....	158573		A29	477 Drive .....	108209		6415BR
Drive; W/33" Belt O.C.; For Walking Tractor .....	916119		6833	487; 519 Drive .....	106769		A54
Rotary 24" Cross Deck; W/37" Belt O.C.; For Walking Tractor .....	176917		6837	562 Drive .....	108209		6415BR
Cross Deck; W/38" Belt O.C.; For Walking Tractor .....	121216		6838	563; 564 Drive .....	106769		A54
Drive; W/31" Belt O.C.; For Walking Tractor .....	158573		A29	649; 663 Drive .....	174224		6866
Drive; W/33" Belt O.C.; For Walking Tractor .....	1608954	2328	6835	709 Drive .....	174486		6949
P.T.O.; For Walking Tractor .....	121078		6835	745; 746 Drive .....	174224		6866
Rotary 32" Cross Deck; For Walking Tractor .....	156231		6842	882 Drive .....	108209		6415BR
Spindle; For Walking Tractor .....	156120		6863	4208; 5212.5; 6216 Drive .....	1665638		6560
<b>P.T.O. Attachments</b>				1600225 Drive .....	174486		6949
349; 460 Drive .....	121078		6835	1690032; 1690033 Drive; W/66" Belt O.C. ....	174224		6866
504; 1690159 Drive .....	1655069		6524BR	Drive; W/69" Belt O.C. ....	1666324		6869
<b>Sicklebar Attachments</b>				1690403; 1690513 Drive .....	1665638		6560
30" Drive; W/33" Belt O.C.; For Walking Tractor .....	1608954	2328		1690542 Drive .....	1666324		6869
Drive; W/34" Belt O.C.; For Walking Tractor .....	174883		6834	1690547; 1690548 Drive .....	1665638		6560
Drive; W/38" Belt O.C.; For Walking Tractor .....	121216		6838	1690770 P.T.O. ....	174224		6866
210; 346; 402; 465 Drive .....	156120		6863	1691521 Drive; 1995-1987 .....	1703466		6484BR
538 Drive .....	101136		A62	1691522 Drive; 1990-1987 .....	1703466		6484BR
548 Drive .....	156120		6863				

Lawn & Garden Equipment

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
<b>Snow Thrower</b>			
Auger; For 26" Models; For Walking Tractor .....	174883		6834
Drive; For 36" Models; For Walking Tractor .....	174911		6844
Trans.; For 24" Models; For Walking Tractor .....	166172		6847
Trans.; For 26" Models; W/46" Belt O.C.; For Walking Tractor .....	1650502		6422BR
Trans.; For 26" Models; W/47" Belt O.C.; For Walking Tractor .....	166172		6847
Trans.; For 26" Models; W/52" Belt O.C.; For Walking Tractor .....	1607967		6639BR
<b>Tiller Attachments</b>			
<b>174; 392</b>			
Drive .....	154273		6942
Trans.; W/45" Belt O.C. ....	152017		B42
Trans.; W/56" Belt O.C. ....	105122		6956
<b>455</b>			
Drive; W/56" Belt O.C. ....	105122		6956
Drive; W/64" Belt O.C. ....	105280		6964
Trans. ....	154273		6942
<b>503</b>			
Drive .....	105340		6996
<b>545</b>			
Drive .....	105287		B85
<b>628</b>			
Drive .....	108505		6870
<b>694</b>			
Drive .....	105340		6996
<b>930</b>			
Drive .....	108505		6870
<b>7116H</b>			
Drive; For 36" Models .....	105340		6996
<b>1600343</b>			
Drive .....	108505		6870
<b>1690039</b>			
Drive .....	105340		6996
<b>1690194</b>			
Drive .....	163011		6525BR
<b>1690287</b>			
Drive .....	1657517		B103
<b>1690393</b>			
Drive .....	163011		6525BR
<b>1691277</b>			
Drive - Rear .....	1673667		6895
<b>Tiller</b>			
Drive; For 12" Models; For Walking Tractor .....	162081		6876
Drive; For 16" Models; For Walking Tractor .....	105066		6958
Drive; For 32" Models; For Walking Tractor .....	105122		6956
Trans.; For 16" Models; For Walking Tractor .....	105067		6951
<b>Vacuum Attachments</b>			
<b>328</b>			
P.T.O. ....	123073		6891
<b>452</b>			
Drive .....	161098		6839
<b>453</b>			
P.T.O. ....	108505		6870
<b>458</b>			
P.T.O. ....	105115		6862

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SIMPLICITY - Continued</b>			
<b>Vacuum Attachments - Continued</b>			
<b>533</b>			
Drive .....	161098		6839
<b>537</b>			
P.T.O. ....	105115		6862
<b>547</b>			
P.T.O. ....	108505		6870
<b>619</b>			
Drive .....	161098		6839
<b>909</b>			
Drive .....	1665706		6839
P.T.O. ....	108505		6870
<b>1690024</b>			
Drive .....	161098		6839
P.T.O. ....	108505		6870
<b>1690402</b>			
P.T.O. ....	1665666		6977
<b>1690503</b>			
Drive .....	1665706		6839
P.T.O. ....	1713549		6478BR
<b>1690990</b>			
Fan .....	1677468		6965
<b>Weed Cutter Attachments</b>			
<b>370</b>			
Drive .....	108151		6863
Spindle .....	124025		6830
<b>SNAPPER</b>			
<b>Mower Attachments</b>			
<b>4ST22</b>			
Blade .....	10109		6840
Trans. ....	10108		6824
<b>6ST27</b>			
Blade .....	10253	2450	6845
Trans. ....	10108	2240	6824
<b>21ESP; 21GSP</b>			
Blade .....	10419	2260	6826
Wheel Drive .....	10056	2270	6827
<b>21HD</b>			
Spindle .....	10034	2290	6829
<b>21HDLP</b>			
Spindle; W/29" Belt O.C. ....	10034	2290	6829
Spindle; W/34" Belt O.C. ....	10467		②6852
<b>22ALP</b>			
Trans. ....	10836	1390	6739
<b>22HD</b>			
Spindle .....	10851		6844
<b>22L; 22LP</b>			
Spindle .....	10747		6856
Trans. ....	10748		6834
<b>26L; 26LP</b>			
Spindle .....	10678		6868
Trans. ....	10729		6843
<b>31HDL</b>			
Spindle .....	10034	2290	6829
<b>32142</b>			
Blade .....	76353		6986
Traction .....	76497		②6441BR
Trans. ....	76498		6936
<b>80199</b>			
Deck .....	19580		②6386
<b>80299</b>			
Deck .....	19594		②6385

②Two Required





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>Mower Attachments - Continued</b>			
80499 Deck .....	19578		Ⓜ6384
481252 Blade To Blade .....	76676		6952
Eng. To Blade .....			6994
Traction .....	76497		Ⓜ6441BR
Trans. ....	76680		6937
M10 Trans. ....	10708	2450	6845
PMA7360 Eng. To Deck .....	38624		6983
PMA7480 Blade To Blade .....	19205		6952
Pro 52 Traction .....	76497		Ⓜ6441BR
Series 1 Eng. To Drive .....	12508		6534BR
SP19C Spindle .....	10085		6835
Trans. ....	10084		6823
SP20B; SP20C; SP20D Spindle .....	10034	2290	6829
Wheel Drive .....	10063	2290	6829
SP21D SP Blade .....	11887		6534BR
Spindle .....	10056	2270	6827
Trans. ....	10063	2290	
ST19C Spindle .....	10085		6835
Trans. ....	10084		6823
ST22 Spindle .....	10109		Ⓜ6840
Trans. ....	10708	2450	6845
ST25 Spindle .....	10451	2410	6841
Trans. ....	10084		6823
ST27 Spindle; W/44" Belt O.C. ....	10252		6844
Spindle; W/45" Belt O.C. ....	10253		6845
Trans. ....	10708	2450	6845
SV21P Blade .....	10849	1255	6380
T10 Trans. ....	10708	2450	6845
TE2 Spindle .....	10063	2290	6829
V21P4; V21PS; V21XP; V21XPS Blade .....	10849	1255	6380
Z4804M Blade .....			A100
Deck .....			6985
<b>Snow Thrower Attachments</b>			
360LTS Blower .....	13939		6376
Drive; W/36" Belt O.C. ....	14716		6836
Drive; W/39" Belt O.C. ....	14717		6839
60376 Idler .....			6854
82099 Blower; W/36 3/4" Belt O.C. ....	13939		6376
Carrier To Blower; W/100" Belt O.C. ....	14225		68100
82597; 82598 P.T.O. ....	14716		6836

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SNAPPER - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
82889 P.T.O. ....	23282		6835
83699 P.T.O.; W/39" Belt O.C. ....	14717		6839
P.T.O.; W/40" Belt O.C. ....	14955		6840
<b>Tiller Attachments</b>			
60330 Belt .....	12561		6854
<b>Vacuum Attachments</b>			
Vacuums P.T.O. ....			6864
<b>SPEEDEX</b>			
<b>Mower Attachments</b>			
3 Blade Mower Belt; For Model S32 .....			6885
Eng. To Variable Speed; For Models S17, S17VS, S18JS, S19, S19JS .....	3926934		6934
Variable Speed To Axle; For Models S17, S17VS, S18JS, S19, S19JS .....			6853
432 - CD Mower Eng. To Variable Speed; For Models S14, S18JS, S19JS .....	3912400		6840
Mower Drive; For Models S17, S17VS, S19 .....	3912510		6851
Variable Speed To Axle; For Models S14, S18JS, S19JS .....	3930250		3V250
436 - CD Mower Eng. To Variable Speed; For Models S18JS, S19JS .....	3912390		6839
Mower Drive; For Models S17, S17VS, S19, S23 .....	3911053		6855
Variable Speed To Axle; For Models S18JS, S19JS .....	3930280		Ⓜ3V280
437 - RA Mower Mower Drive; For Model 1040A .....			6850
Mower Drive; For Models 1240, 1640 .....			6852
Mower Drive; For Models S17, S17VS, S19, S19JS, 820, 840, 1020, 1030, 1040, 1130, 1140 .....	3916854		6854
444 - CD Mower Eng. To Variable Speed; For Models S23, S24, S24VS, 1320, 1420 .....	3926947		6947
Variable Speed To Axle; For Models S23, S24, S24VS, 1320, 1420 .....	3930300		Ⓜ3V300
445 - RA Mower Eng. To Variable Speed; For Models S23, S24, S24VS .....	3912640		6864
Mower Drive; For Model 832D .....	3926680		6968
Mower Drive; For Models 1430, 1630, 1630T, 1632 .....	3923640		6964
Variable Speed To Axle; For Models S23, S24, S24VS .....	3923640		6964
448 - RA Mower Eng. To Variable Speed; For Model 1622 ..			6927
Mower Drive; For Model 1632 .....			6957
Mower Drive; For Model 1832 .....			6958
Mower Drive; For Models 1240, 1640 .....			6852
Variable Speed To Axle; For Model 1622 ..			6956
Brush Bass Belt .....			6944
Front Mount Mower Belt; W/36" Deck .....	3923260		6926
Belt; W/44" Deck .....	3923300		6930
<b>Shredder Attachments</b>			
Shredders Belt; For Model S24VS .....			6864
Belt; For Models S14, S17, S17VS, S19 ...			6861
Belt; For Models S18JS, S19JS .....			6860

ⓂTwo Required

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SPEEDEX - Continued</b>			
<b>Shredder Attachments - Continued</b>			
<b>Shredders - Continued</b>			
Belt; For Models S23, S24 .....	3926680		6968
<b>Sicklebar Attachments</b>			
<b>42"</b>			
Belt; For Model S24VS .....	3923500		6950
Belt; For Models S14, S17, S17VS, S18JS, S19, S19JS .....	3923440		6944
Belt; For Models S23, S24 .....	3923480		6948
<b>46"</b>			
Belt; For Models 820, 840, 1020, 1030, 1040, 1130, 1140 .....	3923440		6944
Belt; For Models 832D, 1320, 1420, 1430, 1630, 1630T, 1632 .....	3911051		6853
<b>Snow Thrower Attachments</b>			
<b>36"</b>			
Belt; For Models S14, S17, S24VS .....			6859
Belt; For Models S17VS, S18JS, S19JS, S19 .....			6857
Belt; For Models S23, S24 .....			6864
<b>44"</b>			
Belt; For Model 1632 .....			6887
Belt; For Models 1430, 1630 .....			6879
Belt; For Models 840, 1030, 1040, 1130, 1140 .....			6874
Belt; For Models S14, S17, S24VS .....			6859
Belt; For Models S17VS, S18JS, S19JS, S19 .....			6857
Belt; For Models S23, S24 .....			6864
<b>Tiller Attachments</b>			
<b>Tiller</b>			
Belt; W/5 H.P. Eng. ....			6850
Belt; W/8 H.P. Eng. ....			6837
<b>SPRINGFIELD</b>			
<b>Mower Attachments</b>			
<b>BM425</b>			
Direct Drive; W/122" Belt O.C. ....	81A120		A120
Direct Drive; W/88" Belt O.C. ....	81A086		6888
<b>MD472</b>			
Deck; W/72" Deck .....	81B180		B180
<b>MR448</b>			
Drive; W/48" Rotary Mower .....	81A128		A128
<b>MR460</b>			
Drive; W/60" Rotary Mower .....	81A144		A144
<b>MR472</b>			
Drive; W/72" Rotary Mower .....	81A180		A180
<b>MX460</b>			
Belt .....	81B158		B158
<b>Reel Mower</b>			
Belt; For Models 3002H, 3003H, 3004H .....	2512	3350	6935
<b>RM74</b>			
Drive .....	83A045		6847
Tractor Drive .....	83A043		6845
<b>Rotary Mower</b>			
Belt; For Models 66CTM, 66CTME; W/30" Belt O.C. ....	61D35	2300	6830
Belt; For Models 66CTM, 66CTME; W/31" Belt O.C. ....	61TR83	2310	6831
<b>Rotary Sweeper Attachments</b>			
<b>RS350</b>			
Brush .....			6889
Drive; W/42" Belt O.C. ....	81A040		6842
Drive; W/90" Belt O.C. ....	81A088		6890
<b>Snow Thrower Attachments</b>			
<b>62SB; 62SBE</b>			
Belt; For Models 66CTM, 66CTME .....	59080		6835

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>SPRINGFIELD - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
<b>SB-48A</b>			
Main Drive; W/65" Belt O.C. ....	81BX62		BX62
Main Drive; W/71" Belt O.C. ....	81BX68		BX68
P.T.O.; W/55" Belt O.C. ....	81A53		6855
P.T.O.; W/61" Belt O.C. ....	81A59		6861
<b>Stump Grinder Attachments</b>			
<b>Stump Grinder</b>			
Belt .....			6846
<b>Trencher Attachments</b>			
<b>Trencher</b>			
Belt .....			6954
<b>STEINER TURF</b>			
<b>Reel Mower Attachments</b>			
<b>RM74</b>			
Drive; For Model 2X4 .....	83A045		6847
Drive; W/45" Belt O.C. ....	83A043		6845
<b>SWISHER</b>			
<b>Trail Mower Attachments</b>			
<b>FC14560BS; FC14560CPKA</b>			
Blade - Center .....	6046HP		7052BR
Blade - Left To Right .....	5058		6777BR
<b>FC14566CPKA</b>			
Blade - Left To Right .....	12527		A128
<b>RC14552CPKA</b>			
Blade Drive .....	14276		6964
<b>TORO</b>			
<b>Aerator Attachments</b>			
<b>Aerator</b>			
Belt; For Power Handle .....	27144	3300	6930
<b>Edger/Trimmer Attachments</b>			
<b>Edger/Trimmer</b>			
Belt; Ser. No. 40127, 40406, 41100, 41101, 41103, 41108; W/25" Belt O.C.; For Power Handle .....	27129	2250	6825
Belt; Ser. No. 40127, 40406, 41100, 41101, 41103, 41108; W/33" Belt O.C.; For Power Handle .....	27159	2330	6833
Belt; Ser. No. 41210, 41211, 41212, 41213, 41219; For Power Handle .....	27133	2310	6831
<b>Generator Attachments</b>			
<b>Generator</b>			
Belt; For Power Handle .....	2714	2300	6830
Pump; For Power Handle .....	27139		6850
<b>Mower Attachments</b>			
<b>0-5722; 05-36MR01; 05-36MR02; 05-36MR03; 05-36MR04; 05-36MR05; 05-36MS01; 05-36MS02; 5-0622; 65-36MS01</b>			
Deck Drive .....	102741		6638BR
<b>75-36MS01; 75-36MS02; 75-36XR01; 75-36XR02; 85-36MR01; 85-36MS01; 85-42MR01; 85-42MS01; 85-48MS01; 95-36MR00</b>			
Deck Drive .....	102741		6638BR
<b>95-36MR01; 95-36MS00; 95-36MS01; 95-42MR01; 95-42MR02; 95-42MS00; 95-48MS00</b>			
Deck Drive .....	102741		6638BR
<b>30162</b>			
Cross Deck .....	446260		6409BR
Deck Drive .....	741330		6573BR
<b>30355</b>			
Gear Box; W/Rear Discharge .....	938457		6696BR



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>30372; 30373</b> Deck Drive .....	938457		6696BR
<b>30548</b> Cross Deck .....	570240		6570BR
<b>30555; 30560</b> Cross Deck .....	271160		6571BR
<b>30562; 30564</b> Cross Deck .....	446260		6409BR
Deck Drive .....	741330		6573BR
<b>30575</b> Deck .....	570240		6570BR
<b>30591; 30593</b> Deck Drive .....	938457		6696BR
<b>30716</b> Gear Box .....	938457		6696BR
<b>30747</b> Deck .....	570240		6570BR
<b>35620</b> Cross Deck .....	271160		6571BR
<b>57358</b> Belt; W/44" Deck .....	576990		6882
<b>78300; 78305; D5-36MR01</b> Deck Drive .....	102741		6638BR
<b>Homelawn Reel Mower</b>			
Belt; Ser. No. 08108; For Power Handle ....	2713	2240	6824
Belt; Ser. No. 10210, 10219, 10610, 10611, 10612, 10613, 10618, 10619; For Power Handle .....	27143	2230	6823
Belt; Ser. No. 10411, 10412, 10413; For Power Handle .....	27157	1250	6725
Belt; Ser. No. 4021; For Power Handle .....	27129	2250	6825
<b>Reel Mower</b>			
Belt; W/34" Belt O.C.; For Lawn Mower .....	27158	2340	6834
Belt; W/39" Belt O.C.; For Lawn Mower .....	27181	2390	6839
<b>Rotary Mower</b>			
Belt; W/17" Belt O.C.; Ser. No. 20212, 20213; W/21" Deck; For Power Handle .....	31183	1170	6717
Belt; W/20" Deck; For Power Handle .....	27166	3240	
Belt; W/30" Belt O.C.; Ser. No. 20212, 20213; W/21" Deck; For Power Handle .....	31182		6730
Belt; W/37" Belt O.C.; For Lawn Mower .....	27173	2370	6837
Belt; W/47" Belt O.C.; Ser. No. 20212, 20213; W/21" Deck; For Power Handle .....	34577		6847
Belt; W/50" Belt O.C.; For Lawn Mower .....	31560	2500	6850
Blade; Ser. No. 20310, 20311; For Power Handle .....	34577		6847
Blade; Ser. No. 20313; For Power Handle .....	34577		6847
Blade; Ser. No. 21000, 21003; For Power Handle .....	35856		6853
Blade; Ser. No. 40207; W/21" Deck; For Power Handle .....	27171	1450	6745
Blade; Ser. No. 43108; W/22" Deck; For Power Handle .....	27171	1450	6745
Blade; Ser. No. 43109; W/22" Deck; For Power Handle .....	27171	1450	6745
Blade; W/23" Belt O.C.; Ser. No. 20210; For Power Handle .....	31662	2230	6823
Blade; W/47" Belt O.C.; Ser. No. 20210; For Power Handle .....	34577		6847
Drive; Ser. No. 20313; For Power Handle ..			6731
Drive; Ser. No. 21000, 21003; For Power Handle .....	35857	1270	6727
Drive; Ser. No. 40207; W/21" Deck; For Power Handle .....	27172	2260	6826
Drive; Ser. No. 43109; W/22" Deck; For Power Handle .....	27172	2260	6826
Drive; W/28" Belt O.C.; Ser. No. 20210; For Power Handle .....	34663	1280	6728
Drive; W/32" Belt O.C.; Ser. No. 20210; For Power Handle .....	37274		6732

②Two Required

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TORO - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>Rotary Mower - Continued</b>			
Eng. To Pulley; Exc. Ser. No. 20211; W/21" Deck; For Power Handle .....	31662	2230	6823
Eng. To Pulley; Ser. No. 20211; W/21" Deck; For Power Handle .....	32733		6825
Pulley To Drive; Ser. No. 20211; W/21" Deck; For Power Handle .....	31663	1270	6727
Traction; Ser. No. 20310, 20311; For Power Handle .....	37274		6732
Traction; Ser. No. 43108; W/22" Deck; For Power Handle .....	27129	2250	6825
<b>Sportlawn Reel Mower</b>			
Belt; W/20", 25" Deck; For Power Handle ..	27143	2230	6823
Belt; W/21" Deck; For Power Handle .....	27157	1250	6725
<b>Snow Thrower Attachments</b>			
<b>32"</b>			
Belt; For Models 55000, 55001, 55100, 55101 .....			3V670
<b>36"</b>			
Belt; For Model 59160 .....	496950		6858
<b>Snow Hound</b>			
Belt; Ser. No. 31000; For Power Handle ....	27110	3310	6931
Belt; Ser. No. 31001, 31101; For Power Handle .....	27183	3310	6931
Belt; Ser. No. 31002, 31003; For Power Handle .....	34058	2300	6830
Belt; Ser. No. 31009; For Power Handle ....	27144	3300	6930
Belt; Ser. No. 31100; For Power Handle ....	27180	3280	
Belt; Ser. No. 31108, 31109, 40106; For Power Handle .....	27138	3290	6929
Belt; Ser. No. 31210; For Power Handle ....	36044	2290	6829
<b>Sprayer Attachments</b>			
<b>Sprayer</b>			
Belt; For Power Handle .....	27169	2700	6870
<b>Tiller Attachments</b>			
<b>Tiller</b>			
Belt; Ser. No. 38121, 38122, 38123; For Power Handle .....	27191		6948
Drive; Ser. No. 38100, 38108, 38110, 38118; For Power Handle .....	27168		6943
<b>TRACTOR SUPPLY</b>			
<b>Mower Attachments</b>			
<b>44-1885</b> Belt; W/32" Deck .....	7540113		6948
<b>1899</b> Blade .....	9303		6725
<b>Snow Thrower Attachments</b>			
<b>1898</b>			
Eng. To Blower; W/6, 7 H.P. Eng. ....	13072		A70
Eng. To Blower; W/8, 10, 12 H.P. Eng. ....	18263		6844
<b>TROY BILT</b>			
<b>Mower Attachments</b>			
<b>42" Mower Deck</b> Blade .....	1728133		6892
<b>P.T.O. Attachments</b>			
<b>P.T.O.</b>			
Drive .....	1741578		6843
<b>TUFF-BILT</b>			
<b>Generator Attachments</b>			
<b>Gen. 5000W</b>			
Belt .....	115111BX38		②BX38
<b>Mower Attachments</b>			
<b>42" Mower</b>			
Belt .....	115111B173		B173

**LAWN ATTACHMENTS**



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>TUFF-BILT - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>42" Mower - Continued</b>			
Clutch .....	115111BX38		BX38
Drive .....	115111B144		B144
<b>59" Mower</b>			
Blade Drive .....	115111B210		B210
Clutch .....	115111BX38		BX38
<b>60" Mower</b>			
Clutch .....	115111BX38		BX38
Drive .....	115111B158		B158
<b>UNICO</b>			
<b>Mower Attachments</b>			
<b>Rotary Mower</b>			
Belt; W/105" Belt O.C. ....	7540125		6428BR
Belt; W/48" Belt O.C. ....	7540113	3480	6948
<b>Snow Thrower Attachments</b>			
<b>Tractor</b>			
Belt; W/7 H.P. Eng. ....	7540113	3480	6948
<b>UNIVERSAL PROCESS CO.</b>			
<b>Mower Attachments</b>			
<b>36" Mower</b>			
Belt .....	2480		6848
<b>44" Mower</b>			
Belt .....	3450	3450	6945
<b>WESTERN AUTO</b>			
<b>Mower Attachments</b>			
<b>193-762; 193-962</b>			
Blade; W/105" Belt O.C. ....	7540125		6428BR
Blade; W/99 5/8" Belt O.C. ....	7540181		7014BR
Eng. To Deck .....	7540180		6510BR
<b>2642</b>			
Blade .....	11793		6989
Eng. To Deck .....	36806		6953
<b>2648</b>			
Blade .....	200982		6878
Eng. To Deck .....			6981
<b>3666; 3769; 5511</b>			
Blade .....	9303	1250	6725
<b>7142</b>			
Blade .....			6866
<b>7148</b>			
Blade .....	200982		6878
Eng. To Deck .....			6981
<b>7551</b>			
Blade .....	7540125		6428BR
<b>7552</b>			
Blade .....	7540181		7014BR
Eng. To Deck .....	7540180		6510BR
<b>Mower - Lawn Mower</b>			
Blade - Left .....	60D56	2310	6831
Blade - Right .....	60D57	2300	6830
<b>Snow Thrower Attachments</b>			
<b>2552; 2553</b>			
Eng. To J.S. ....	37756		6856
J.S. To Snow Thrower; W/83" Belt O.C. ....	37757		6883
J.S. To Snow Thrower; W/86" Belt O.C. ....	209581		6886
<b>2556</b>			
Eng. To J.S. ....	37756		6856
J.S. To Snow Thrower .....	212261		6887
<b>2607</b>			
Eng. To Blower .....	38263	2450	6845
<b>10136</b>			
Eng. To J.S. ....	37756		6856

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WESTERN AUTO - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
<b>10136 - Continued</b>			
J.S. To Snow Thrower .....	212261		6887
<b>Tiller Attachments</b>			
<b>2531</b>			
Secondary .....			6840
<b>WHEEL HORSE</b>			
<b>Cutter Bar Attachments</b>			
<b>CBR36</b>			
Belt; W/28" Belt O.C. ....	1577		6828
Belt; W/37" Belt O.C. ....	1578		6737
<b>Generator Attachments</b>			
<b>97-30GN; 97-50GN</b>			
Belt .....	107740		6984
<b>Mower Attachments</b>			
<b>05-32YS01</b>			
Spindle .....	8430		6859
<b>05-36MR01; 05-36MR03; 05-36MR04;</b>			
<b>05-36MS01</b>			
Drive .....	102741		6638BR
Spindle .....	8411	2770	6877
<b>05-36XR01; 05-36XR04; 05-36XR05;</b>			
<b>05-36XS01</b>			
Drive .....	106533		6840
Spindle .....	106751		6880
<b>05-36YR01</b>			
Drive .....	102741		6638BR
Spindle .....	8411	2770	6877
<b>05-37MS05; 05-37MS06</b>			
Drive .....	108195		6867
Spindle .....	110082		A46
<b>05-37SL01</b>			
Belt .....	113141		6876
<b>05-42MR01; 05-42MR02; 05-42MR03;</b>			
<b>05-42MR04</b>			
Drive .....	108834		6898
Spindle .....	106125		6889
<b>05-42MS01; 05-42MS02</b>			
Spindle .....	6738		6886
<b>05-42RK01</b>			
Drive .....	113912	2440	
Spindle .....	106516		A81
<b>05-42SB05</b>			
Drive .....			6841
Spindle .....	106516		A81
<b>05-42SK01</b>			
Drive .....	114718		6846
Spindle .....	106516		A81
<b>05-42SM04</b>			
Drive .....			6841
Spindle .....	106516		A81
<b>05-42SY01</b>			
Drive .....	116160		6972
<b>05-42XR05; 05-42XR06</b>			
Drive .....			6841
Spindle .....	106516		A81
<b>05-48MS01; 05-48MS02</b>			
Spindle .....	1594		6781BR
<b>05-48XS01; 05-48XS02</b>			
Drive .....			68105
Spindle .....	1594		6781BR
<b>5-0200; 5-0201</b>			
Blade .....	8976		6855
Main Drive .....	8975		6858



Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHEEL HORSE - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>5-0400</b>			
Traction .....	104290	1293	
<b>5-0481</b>			
Blade .....	1594		6781BR
Deck .....	9783		6871
<b>5-0600; 5-0601</b>			
Drive .....	9360		6896
Mower .....	8411	2770	6877
<b>5-0602</b>			
Blade .....	8411	2770	6877
Deck .....	102607		6889
<b>5-0611</b>			
Drive .....	8412		6886
Mower .....	8411	2770	6877
<b>5-0620</b>			
Blade .....	8411	2770	6877
Deck .....	102607		6889
<b>5-0621; 5-0622</b>			
Mower; W/89" Belt O.C. ....	102607		6889
Mower; W/97" Belt O.C. ....	102741		6638BR
Spindle .....	8411	2770	6877
<b>5-0701; 5-0702</b>			
Drive .....	8412		6886
Mower .....	8411	2770	6877
<b>5-0710; 5-0711</b>			
Drive .....	9360		6896
Mower .....	8411	2770	6877
<b>5-0720</b>			
Blade .....	8411	2770	6877
Deck .....	102607		6889
<b>5-0721; 5-0722</b>			
Mower; W/89" Belt O.C. ....	102607		6889
Mower; W/97" Belt O.C. ....	102741		6638BR
Spindle .....	8411	2770	6877
<b>5-1000; 5-1001</b>			
Blade .....	9782		6869
Drive .....	6738		6886
<b>5-1010; 5-1011</b>			
Deck; W/103" Belt O.C. ....	102742		6378
Deck; W/107" Belt O.C. ....	1594		6781BR
Deck; W/86" Belt O.C. ....	6738		6886
<b>5-1200; 5-1201; 5-1202</b>			
Blade .....	1594		6781BR
Deck .....	9783		6871
<b>5-1210; 5-1211</b>			
Deck; W/103" Belt O.C. ....	102742		6378
Deck; W/107" Belt O.C. ....	1594		6781BR
Deck; W/86" Belt O.C. ....	6738		6886
<b>5-1220; 5-1221</b>			
Drive .....			68105
Eng. To Deck .....			B103
Spindle .....	1594		6781BR
<b>5-1361; 5-1362</b>			
Blade .....	1563	2390	
Speed Drive .....	1578		6737
<b>5-1421</b>			
Blade .....	6738		6886
Main Drive .....	6737		6869
<b>5-1422; 5-1423</b>			
Blade .....	9782		6869
Drive .....	6738		6886
<b>5-1481</b>			
Blade; W/107" Belt O.C. ....	1594		6781BR
Blade; W/71" Belt O.C. ....	6771		6871
<b>5-1482; 5-1483</b>			
Blade .....	1594		6781BR

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHEEL HORSE - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>5-1482; 5-1483 - Continued</b>			
Deck .....	9783		6871
<b>5-2321; 5-2322; 5-2361; 5-2362</b>			
Drive .....	1578		6737
Spindle .....	7430		6828
<b>5-2365</b>			
Drive .....	8412		6886
Mower .....	8411	2770	6877
<b>5-3322</b>			
Blade .....	1555		6844
<b>5-5481</b>			
Blade .....	1594		6781BR
Main Drive .....	1595		6867
<b>5-7361; 5-7362</b>			
Drive .....	8412		6886
Mower .....	8411	2770	6877
<b>5-7365; 5-7366</b>			
Drive .....	9360		6896
Mower .....	8411	2770	6877
<b>5-8321</b>			
Blade .....	8976		6855
Drive .....	8975		6858
<b>15-42RC01</b>			
Drive .....	108834		6898
Spindle .....	106125		6889
<b>15-42SC01; 15-42SC02; 15-48SC01; 15-48SC02</b>			
Belt; W/42" Spindle .....	6738		6886
Belt; W/48" Spindle .....	1594		6781BR
Drive .....	102742		6378
<b>63-05BF</b>			
Blade .....	225360		6863
<b>65-36MS; 65-36XR</b>			
P.T.O. ....	102741		6638BR
Spindle .....	8411	2770	
<b>65-42MR</b>			
Mower .....	102741		6638BR
Spindle .....	6738		6886
<b>65-42MS; 65-48MS</b>			
Deck; W/103" Belt O.C. ....	102742		6378
Deck; W/107" Belt O.C. ....	1594		6781BR
Deck; W/86" Belt O.C. ....	6738		6886
<b>65-48XS</b>			
Drive .....			68105
Eng. To Deck .....			B103
Spindle .....	1594		6781BR
<b>73-05BF</b>			
Blade .....	225360		6863
<b>75-36MR</b>			
Drive .....	105477		6840
Mower .....	105476		A78
<b>75-36MS; 75-36XR</b>			
P.T.O. ....	102741		6638BR
Spindle .....	8411	2770	
<b>75-36XS</b>			
Drive .....	105477		6840
Mower .....	105476		A78
<b>75-42MR</b>			
Mower .....	102741		6638BR
Spindle; Early .....	6738		6886
Spindle; Late .....	106125		6889
<b>75-42MS; 75-48MS</b>			
Blade .....	1594		6781BR
Deck .....	102742		6378
Spindle .....	6738		6886

Lawn & Garden Equipment



LAWN ATTACHMENTS



Lawn & Garden Equipment

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHEEL HORSE - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>75-48XS</b>			
Deck .....	1594		6781BR
<b>85-36MR; 85-36MS</b>			
Drive .....	102741		6638BR
Spindle .....	8411	2770	6877
<b>85-36XR; 85-36XS</b>			
Deck .....	106533		6840
Spindle .....	106751		6880
<b>85-42MR</b>			
Mower .....	102741		6638BR
Spindle .....	106125		6889
<b>85-42MS</b>			
Deck; W/103" Belt O.C. ....	102742		6378
Deck; W/107" Belt O.C. ....	1594		6781BR
Deck; W/86" Belt O.C. ....	6738		6886
<b>85-42XR</b>			
Drive .....	106523		6841
Spindle .....	106516		A81
<b>85-48MS</b>			
Deck; W/103" Belt O.C. ....	102742		6378
Deck; W/107" Belt O.C. ....	1594		6781BR
Deck; W/86" Belt O.C. ....	6738		6886
<b>85-48XS</b>			
Drive .....			68105
Eng. To Deck .....			B103
Spindle .....	1594		6781BR
<b>95-32MS</b>			
Belt .....	107298		6872
<b>95-36MR; 95-36MS</b>			
Drive .....	102741		6638BR
Spindle .....	8411	2770	6877
<b>95-36XR; 95-36XS</b>			
Deck .....	106533		6840
Spindle .....	106751		6880
<b>95-36YR</b>			
Drive .....	107320		6860
Spindle .....	8411	2770	6877
<b>95-42MR</b>			
Mower .....	102741		6638BR
Spindle .....	106125		6889
<b>95-42MS</b>			
Deck; W/103" Belt O.C. ....	102742		6378
Deck; W/107" Belt O.C. ....	1594		6781BR
Deck; W/86" Belt O.C. ....	6738		6886
<b>95-42XR</b>			
Drive .....	106523		6841
Spindle .....	106516		A81
<b>95-48MS</b>			
Deck; W/103" Belt O.C. ....	102742		6378
Deck; W/107" Belt O.C. ....	1594		6781BR
Deck; W/86" Belt O.C. ....	6738		6886
<b>95-48XS</b>			
Drive .....			68105
Eng. To Deck .....			B103
Spindle .....	1594		6781BR
<b>RL366; RL367</b>			
Belt; W/37" Belt O.C. ....	1578		6737
Belt; W/39" Belt O.C. ....	1563	2390	6839
<b>RL426</b>			
Belt; W/69" Belt O.C. ....	6737		6869
Belt; W/86" Belt O.C. ....	6738		6886
<b>RL486; RL487</b>			
Belt; W/107" Belt O.C. ....	1594		6781BR
Belt; W/71" Belt O.C. ....	6771		6871
<b>RM323; RM324</b>			
Belt; W/28" Belt O.C. ....	7430		6828

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHEEL HORSE - Continued</b>			
<b>Mower Attachments - Continued</b>			
<b>RM323; RM324 - Continued</b>			
Belt; W/37" Belt O.C. ....	1578		6737
<b>RM326; RM327</b>			
P.T.O. ....	1577		6828
Spindle .....	1578		6737
<b>RM363; RM364</b>			
Belt; W/28" Belt O.C. ....	7430		6828
Belt; W/37" Belt O.C. ....	1578		6737
<b>RM366; RM367</b>			
P.T.O. ....	1577		6828
Spindle .....	1578		6737
<b>RM425</b>			
Mower .....			②6829
<b>RM3262</b>			
Belt; W/28" Belt O.C. ....	7430		6828
Belt; W/37" Belt O.C. ....	1578		6737
<b>RMR32</b>			
Belt; W/24" Belt O.C. ....	1554	2240	6824
Belt; W/30" Belt O.C. ....	1561		6830
<b>RMR483; RMR484; RMR485</b>			
Belt; W/107" Belt O.C. ....	1594		6781BR
Belt; W/67" Belt O.C. ....		2670	6867
<b>RMR3661; RMR3662</b>			
Belt; W/28" Belt O.C. ....	7430		6828
Belt; W/37" Belt O.C. ....	1578		6737
<b>P.T.O. Kits</b>			
<b>8-3211</b>			
Belt .....	7776		6885
<b>66</b>			
Drive; W/37" Belt O.C. ....	1552	2370	6837
Drive; W/42" Belt O.C. ....	1550	2420	6842
<b>Sicklebar Attachments</b>			
<b>7-1311; 7-1312; SML506; SMS506</b>			
Belt; W/38" Belt O.C. ....	6573		6838
Belt; W/59" Belt O.C. ....	1588		6859
<b>Snow Thrower Attachments</b>			
<b>06-42ST01; 06-42ST02</b>			
Drive .....	9750		6969
<b>06-48ST01; 06-48SX01</b>			
Drive .....	200170		6853
<b>6-0201; 6-0202</b>			
Belt .....	102743		B64
<b>6-1211</b>			
Belt .....	1576		6870
<b>6-2211; 6-3211</b>			
Drive .....	1589		6857
<b>6-3251</b>			
Belt .....	100129		6950
<b>6-6213</b>			
Drive .....	9750		6969
<b>6-7212</b>			
Auger .....	8677		6852
<b>6-7451; 6-7452</b>			
Drive .....	200170		6853
<b>6-9111</b>			
Belt .....	8231		6870
<b>6-9112</b>			
Drive .....	9750		6969
<b>6-9121; 6-9122</b>			
Belt .....	8160		6983
<b>6-9131</b>			
Belt .....	102743		B64

②Two Required





Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHEEL HORSE - Continued</b>			
<b>Snow Thrower Attachments - Continued</b>			
66-42ST; 76-42ST Drive .....	9750		6969
76-48ST01 Drive .....	200170		6853
86-42ST Drive .....	9750		6969
86-48ST01; 86-48SX01 Drive .....	200170		6853
96-42ST Drive .....	9750		6969
96-48ST01; 96-48SX01 Drive .....	200170		6853
79360 Belt .....	9750		6969
ST374; ST375; ST376 Belt .....	1576		6870
ST400; ST500; ST550 Trans. ....	1569		6829
<b>Tiller Attachments</b>			
7-1211; RT366; RT367 Forward .....	1586		6876
Reverse .....	7358		6866
<b>Vacuum Attachments</b>			
7-2612; 7-2613; 67-42VC; 77-42VC; 77-42VX Drive .....	1594		6781BR
Impeller .....	1580		6831
<b>WHITE OUTDOOR PRODUCTS</b>			
<b>Mower Attachments</b>			
0042T Deck; W/48" Belt O.C. ....	9003007		6848
Deck; W/53" Belt O.C. ....	9003006		6853
52" Mower Deck Belt; W/123" Belt O.C. ....	9003005B		B120
62" Mower Deck Drive; For Model 0062T .....	9003012		BX55
990-031 Blade .....	7540125		6428BR
990-206 Deck .....	320063541		6354
993 Belt; W/50" Deck .....	7540197		6604BR
<b>Snow Thrower Attachments</b>			
486 Drive .....	7540185		6849
491 Drive .....	7540299		6849
756 Drive; W/48" Belt O.C. ....	7540283A		6848
Drive; W/52" Belt O.C. ....			6852
830 Drive .....	7540229		6852
832; 930 Drive .....	7540206		6850
<b>Tiller Attachments</b>			
766 Drive .....	7540253		6843
<b>WHITE STORES</b>			
<b>Mower Attachments</b>			
87-90 Eng. To Deck .....	7540113	3480	6948

Application	OEM No.	Standard Belt No.	Premium Belt No.
<b>WHITE STORES - Continued</b>			
<b>Mower Attachments - Continued</b>			
87-126 Blade .....	7540125		6428BR
<b>WOODS</b>			
<b>Mower Attachments</b>			
9144 Bat Wing Deck - Center .....	28975		6584BR
Deck - Left & Right .....	29010		B83
<b>YANMAR</b>			
<b>Mower Attachments</b>			
Ranger Blade .....			6978
Drive .....			B105
YMR48 Blade .....			6964
YMR59; YMR60 Blade .....	055111		ⓂB71
<b>YARD-MAN</b>			
<b>Mower Attachments</b>			
6992-0-6 Deck .....	7540197		6604BR
19765 Blade .....	7540250		6853
Deck .....	7540251		6809BR
19798C Blade; W/36" Deck .....	7540250		6853
Trans.; W/36" Deck .....	7540214		6850
19931 Blade To Blade .....	7540260		5716
Eng. To Deck .....	7540230		6755BR
19935 Blade .....	7540230		6755BR
Deck .....	7540246		6354
19957 Deck .....	7540230		6755BR
Drive .....	7540181		7014BR
19958 Drive .....	7540230		6755BR
Spindle .....	7540215		6379
19982-0 Deck .....	7540125		6428BR
19992-0; 19993 Deck .....	7540197		6604BR
Y834P Deck - Left .....	7540364		6482BR
Deck - Right .....	7540291		6641BR
<b>P.T.O. Kits</b>			
19952 P.T.O. ....	7540229		6852
<b>Snow Thrower Attachments</b>			
190-930A Lower Drive .....	7540236		6885
Upper Drive .....	7540206	2500	6850
3520-0 Belt .....			6840
3530-0 Belt .....			6836
19469 Auger .....	7540236		6885
Deck .....	7540185		6849
19471 Drive .....	7540108	2460	6846

ⓂTwo Required

LAWN ATTACHMENTS



Application	OEM No.	Standard Belt No.	Premium Belt No.
-------------	---------	-------------------	------------------

**YARD-MAN - Continued**

**Snow Thrower Attachments - Continued**

<b>19930; 19930-1</b>			
Auger .....	7540236		<b>6885</b>
Drive .....	7540206		<b>6850</b>

**Tiller Attachments**

<b>19766</b>			
Drive .....	7540253		<b>6843</b>

Lawn & Garden Equipment



Manufacturers' Part Number Shown for Reference Only

Application	OEM No.	Our No.
<b>AMADAS INDUSTRIES</b>		
<b>9900</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2003		
Belt - Elevator Fan .....	2B85	2/B85
Belt - Elevator J.S. & Cleaner Fan .....	C75	C75
Belt - Hyd. Pump - Left Side .....	C75	C75
2000		
Belt - Elevator Fan .....	C75	C75
Belt - Hyd. Pump .....	C75	C75
Belt - Spreader .....	B225	B225
<b>9960</b>		
<b>John Deere 6-Cyl. 6.8 L Diesel</b>		
2006		
Belt - Elevator Fan J.S. ....	C75	②C75
Belt - Hyd. Pump .....	C75	C75
Belt - Unloader Auger; W/Hyd. Pump .....	C67	②C67
2005-2004		
Belt - Elevator Fan J.S. ....	C75	②C75
Belt - Hyd. Pump .....	C75	C75
Belt - Unloader Auger; W/Hyd. Pump .....	C67	②C67
Belt - Vine Spreader .....	B225	B225
2003		
Belt - Elevator Fan J.S. ....	C75	②C75
Belt - Hyd. Pump - Left Side .....	C75	C75
<b>CASE</b>		
<b>120SP</b>		
<b>Case 400</b>		
1956		
Hose - Upper .....		24228
Hose - Lower .....		≠20065
		or ●25472
<b>150</b>		
<b>Case 400</b>		
1958-1956		
Belt - Fan & Gen. ....	011139AB	▲9490HD
Hose - Upper .....		≠23562
Hose - Lower .....		●26509
<b>600SP</b>		
<b>Case</b>		
1965-1961		
Belt - Fan, W.P. & Gen. ....	A49149	▲9476HD
Belt - Hyd. Pump .....	F22503	TR22461
Belt - V.P. ....		7335
Hose - Upper .....		≠20611
		or ●26510
Hose - Lower .....		●26603
<b>660SP</b>		
<b>Case A201D Diesel</b>		
1970-1961		
Belt - Fan, W.P. & Gen. ....	A49149	▲9476HD
Belt - Hyd. Pump .....	F22503	TR22461
Belt - V.P. ....		7335
Hose - Upper .....		●26510
<b>Case A201G</b>		
1970-1961		
Belt - Fan, W.P. & Gen. ....	A49149	▲9476HD
Belt - Hyd. Pump .....	F22503	TR22461
Belt - V.P. ....		7335
Hose - Upper .....		≠20611
		or ●26510
Hose - Lower .....		●26603

Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>800SP</b>		
<b>Case 709D Diesel</b>		
1962-1959		
Belt - Fan & Gen. ....	A20383	▲9510HD
Belt - Hyd. Pump .....	F8047	TR22545
<b>Case 719G</b>		
1962-1959		
Belt - Fan & Gen. ....	A20383	▲9510HD
Belt - Hyd. Pump .....	F8047	TR22545
<b>Case A251G</b>		
1962-1959		
Belt - Fan & Gen. ....	A11444	▲9505HD
Belt - Hyd. Pump .....	F8047	TR22545
Hose - Upper .....		23562
<b>Case A267D Diesel</b>		
1962-1959		
Belt - Fan & Gen. ....	A11444	▲9505HD
Belt - Hyd. Pump .....	F8047	TR22545
Hose - Upper .....		23562
<b>900SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1966-1965		
Belt - Fan & Gen. ....	F20129	7555
Belt - Gov. ....	F20128	7440
Hose - Upper .....		●25476
<b>960</b>		
<b>Chrysler 6-Cyl. 225</b>		
1970-1961		
Belt - Fan & Gen. ....	F20129	7555
Belt - Gov. ....	F20128	7440
Hose - Upper .....		●25476
<b>1000SP</b>		
<b>Case 4-Cyl. 284</b>		
1962-1959		
Belt - Fan & Gen. ....	A11444	▲9505HD
Belt - Hyd. Pump .....	F8047	TR22545
<b>Case 4-Cyl. 301 Diesel</b>		
1962-1959		
Belt - Fan & Gen. ....	A11444	▲9505HD
Belt - Hyd. Pump .....	F8047	TR22545
Hose - Upper .....		23562
<b>Case 709BF Diesel</b>		
1962-1959		
Belt - Fan & Gen. ....	A20383	▲9510HD
Belt - Hyd. Pump .....	F8047	TR22545
<b>Case 719BF</b>		
1962-1959		
Belt - Fan & Gen. ....	A20383	▲9510HD
Belt - Hyd. Pump .....	F8047	TR22545
<b>Case 719G</b>		
1962-1959		
Hose - Upper .....		23562
<b>1010SP</b>		
<b>Case 4-Cyl. 284</b>		
1965-1963		
Belt - Fan & Gen. ....	A11444	▲9505HD
Belt - Hyd. Pump .....	F8047	TR22545
Hose - Upper .....		23562
<b>Case 4-Cyl. 301 Diesel</b>		
1965-1963		
Belt - Fan & Gen. ....	A11444	▲9505HD

②Two Required ≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>1010SP - Continued</b>		
<b>Case 4-Cyl. 301 Diesel - Continued</b>		
1965-1963 - Continued		
Belt - Hyd. Pump .....	F8047	TR22545
Hose - Upper .....		23562
<b>1060</b>		
<b>Chrysler LH318</b>		
1970-1961		
Belt - Fan & Gen. ....	F12793	7525
Belt - Gov. ....	F12672	7460
Belt - Hyd. Pump .....	F8047	TR22545
Hose - Upper .....		●25476
<b>1160; 1660</b>		
<b>Chrysler LH318</b>		
1970-1961		
Belt - Fan & Gen. ....	F12793	7525
Belt - Gov. ....	F12672	7460
Belt - Hyd. Pump .....	F8047	TR22545
Hose - Upper .....		●25476
<b>Chrysler LH318 Diesel</b>		
1970-1961		
Belt - Fan & Gen. ....	F12793	7525
Belt - Gov. ....	F12672	7460
Belt - Hyd. Pump .....	F8047	TR22545
Hose - Upper .....		●25476
<b>SP9</b>		
<b>Case D</b>		
1955-1949		
Belt - Fan; Ser. No. 5502386 & Before .....	02696AB1	TR30467
Belt - Gen. ....	06344AB	TR24438
Hose - Upper .....		24228
Hose - Lower .....		②20065
		or ●25472
<b>SP12</b>		
<b>Case D</b>		
1956-1949		
Belt - Fan; Ser. No. 5502386 & Before .....	02696AB1	TR30467
Belt - Gen. ....	06344AB	TR24438
Hose - Upper .....		24228
Hose - Lower .....		②20065
		or ●25472
<b>CASE IH</b>		
<b>1620</b>		
<b>Case 6-Cyl. 358 Diesel</b>		
1992-1990		
Belt - A.C.; W/41 7/8" Belt O.C. ....	1250587C1	▲9415HD
Belt - A.C.; W/54 3/8" Belt O.C. ....	280210C2	▲9440HD
Belt - Aux. Pump .....	191288C2	C92
Belt - Fan & Alt. ....	J911565	▲K080580HD
Belt - Feeder; W/O Rock Trap .....	186377C1	C128
Belt - Tailings Elevator .....	674965R1	C101
1989-1986		
Belt - A.C. ....	280210C2	▲9440HD
Belt - Aux. Pump .....	191288C2	C92
Belt - Fan & Alt. ....	130724C91	②▲9700HD
Belt - Feeder; W/O Rock Trap .....	186377C1	C128
Belt - Tailings Elevator .....	674965R1	C101
<b>1640</b>		
<b>Case 6-Cyl. 436 Diesel</b>		
1992-1990		
Belt - A.C.; W/5 1/4" Clutch .....	L72739	▲9430HD
Belt - A.C.; W/O 5 1/4" Clutch .....	396829R1	▲9440HD
Belt - Fan & Alt. ....	J911565	▲K080580HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>1640 - Continued</b>		
<b>Case 6-Cyl. 436 Diesel - Continued</b>		
1989		
Belt - A.C.; W/5 1/4" Clutch .....	L72739	▲9430HD
Belt - A.C.; W/O 5 1/4" Clutch .....	396829R1	▲9440HD
Belt - Fan & Alt.; W/V-Ribbed Belt .....	J911565	▲K080580HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
1988-1986		
Belt - A.C. ....	164550R2	▲9425HD
Belt - Fan J.S.; W/76" Drive .....	610521R1	B71
Belt - Fan J.S.; W/O 76" Drive .....	191305C1	C108
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
<b>1644</b>		
<b>Case 6-Cyl. 359 Diesel</b>		
1994-1992		
Belt - A.C. ....	1250587C1	▲9415HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Fan, Alt. & W.P. ....	J911565	▲K080580HD
Belt - Straw Chopper .....	1315265C1	BP95
<b>1660</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1992-1991		
Belt - A.C.; W/5 1/4" Clutch .....	L72739	▲9430HD
Belt - A.C.; W/O 5 1/4" Clutch .....	396829R1	▲9440HD
Belt - Fan & Alt.; W/Cross Flow Cleaning System .....	J911572	▲K080610HD
Belt - Fan & Alt.; W/O Cross Flow Cleaning System .....	J911574	▲K080626HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
1990		
Belt - A.C.; W/O 5 1/4" Clutch .....	396829R1	▲9440HD
Belt - Fan & Alt.; W/Cross Flow Cleaning System .....	J911572	▲K080610HD
Belt - Fan & Alt.; W/O Cross Flow Cleaning System .....	J911574	▲K080626HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
1989		
Belt - A.C.; W/5 1/4" Clutch .....	L72739	▲9430HD
Belt - A.C.; W/O 5 1/4" Clutch .....	396829R1	▲9440HD
Belt - Fan & Alt.; Ser. No. 38346 & After; W/Cross Flow Cleaning System .....	J911572	▲K080610HD
Belt - Fan & Alt.; Ser. No. 38346 & After; W/O Cross Flow Cleaning System .....	J911574	▲K080626HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
1988-1986		
Belt - A.C. ....	164550R2	▲9425HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
<b>1666</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1994-1992		
Belt - A.C. ....	396829R1	▲9440HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Fan, Alt. & W.P. ....	J911572	▲K080610HD
Belt - Straw Chopper .....	1315265C1	BP95
<b>1670</b>		
<b>IH 6-Cyl. 466 Diesel</b>		
1992-1989		
Belt - A.C. ....	1250587C1	▲9415HD
Belt - Aux. Pump .....	191288C2	C92
Belt - Fan J.S. ....	188213C1	C124

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>1670 – Continued</b>		
<b>IH 6-Cyl. 466 Diesel – Continued</b>		
<b>1992-1989 – Continued</b>		
Belt - Fan, Alt. & W.P. ....	130724C91	▲9700HD
Belt - Feeder; W/O Rock Trap .....	186377C1	C128
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
<b>1680</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
<b>1992-1989</b>		
Belt - A.C.; W/5 1/4" Clutch .....	L72739	▲9430HD
Belt - A.C.; W/O 5 1/4" Clutch .....	1250587C1	▲9415HD
Belt - Fan & A.C. ....	J911574	▲K080626HD
Belt - Fan J.S. ....	191305C1	C106
Belt - Straw Chopper .....	1315266C1	BP108
Hose - Lower .....		②24432
<b>1988-1986</b>		
Belt - A.C. ....	1250587C1	▲9415HD
Belt - Aux. Pump .....	191288C2	C92
Belt - Fan J.S.; W/76" Drive .....	610521R1	B71
Belt - Fan J.S.; W/O 76" Drive .....	188213C1	C124
Belt - Straw Chopper .....	1315266C1	BP108
Hose - Lower .....		②24432
<b>1688</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
<b>1994-1992</b>		
Belt - A.C. ....	396829R1	▲9440HD
Belt - Fan J.S. ....	188213C1	C124
Belt - Fan, Alt. & W.P. ....	J911572	▲K080610HD
Belt - Straw Chopper .....	1315266C1	BP108
<b>2144</b>		
<b>Case 6-Cyl. 436 Diesel</b>		
<b>1997-1995</b>		
Belt - A.C. ....	1250587C1	▲9415HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Fan, Alt. & W.P. ....	J911565	▲K080580HD
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
<b>2166</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
<b>1997-1995</b>		
Belt - Serpentine - Fan, W.P. & Alt. ....	J911572	▲K080610HD
Belt - A.C. ....	396829R1	▲9440HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
<b>2188</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
<b>1997-1995</b>		
Belt - Serpentine - Fan, W.P. & Alt. ....	J911572	▲K080610HD
Belt - A.C. ....	396829R1	▲9440HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
<b>2344</b>		
<b>Case 6-Cyl. 359 Diesel</b>		
<b>2002-1998</b>		
Belt - A.C. ....	164550R2	▲9425HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Fan, Alt. & W.P. ....	J911565	▲K080580HD
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
<b>2366</b>		
<b>Case 6-Cyl. 8.3 L Diesel</b>		
<b>2004-2003</b>		
Belt - Serpentine - Fan, W.P. & Alt. ....	A78022	▲K080790HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Grain Tank Unloader .....	191290C1	C130

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>2366 – Continued</b>		
<b>Case 6-Cyl. 8.3 L Diesel – Continued</b>		
<b>2004-2003 – Continued</b>		
Belt - Straw Chopper .....	1315265C1	BP95
Tensioner Assy. - Fan, W.P. & Alt. ....	87436755	38516
<b>2002-1998</b>		
Belt - Serpentine - Fan, W.P. & Alt. ....	J911572	▲K080610HD
Belt - A.C. ....	396829R1	▲9440HD
Belt - Fan J.S. ....	191305C1	C108
Belt - Grain Tank Unloader .....	191290C1	C130
Belt - Straw Chopper .....	1315265C1	BP95
<b>2377</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
<b>2006</b>		
Belt - Serpentine - Fan .....	A78022	▲K080790HD
<b>2388</b>		
<b>Case 6-Cyl. 8.3 L Diesel</b>		
<b>2006-2003</b>		
Belt - Serpentine - Fan, W.P. & Alt. ....	A78022	▲K080790HD
Belt - A.C. ....	396829R1	▲9440HD
Belt - Fan J.S. ....	188213C1	C124
Belt - Straw Chopper .....	1315266C1	BP108
Tensioner Assy. - Serpentine .....	87436755	38516
<b>2002-1998</b>		
Belt - Serpentine - Fan, W.P. & Alt. ....	J911572	▲K080610HD
Belt - A.C. ....	396829R1	▲9440HD
Belt - Fan J.S. ....	188213C1	C124
Belt - Straw Chopper .....	1315266C1	BP108
<b>AFX2577</b>		
<b>Case 6-Cyl. 8.3 L Diesel</b>		
<b>2008</b>		
Belt - Serpentine - Fan, W.P. & Alt. ....	A78022	▲K080790HD
Belt - A.C. ....	87311867	▲9370HD
Belt - Straw Chopper .....	1315266C1	BP108
<b>2007</b>		
Belt - A.C. ....	87311867	▲9370HD
Belt - Fan, Alt. & W.P. ....	A78022	▲K080790HD
<b>AFX7010</b>		
<b>Case IH 6-Cyl. 9.0 L Diesel</b>		
<b>2008-2005</b>		
Belt - Serpentine - Fan .....	500371653	▲K100640HD
<b>AFX8010</b>		
<b>Case IH 6-Cyl. 10.3 L Diesel</b>		
<b>2008-2007</b>		
Belt - Serpentine - Fan .....	87282305	▲K100615HD
<b>CATERPILLAR</b>		
<b>Lexion 485R</b>		
<b>Caterpillar C12 Diesel</b>		
<b>2004-2001</b>		
Tensioner Assy. - Fan .....	1900642	38508
<b>CHALLENGER</b>		
<b>660</b>		
<b>Caterpillar C9 Diesel</b>		
<b>2008-2006</b>		
Belt - Serpentine - Alt. & A.C. ....	2271364	▲K080816HD
Belt - Rotary Screen .....	71396754	A68
Belt - Spreader J.S. ....	227455M1	C126
<b>2005</b>		
Belt - Serpentine - Alt. & A.C. ....	2271364	▲K080816HD
Belt - Chopper - Rear .....	71388712	C210
Belt - Spreader J.S. ....	227455M1	C126
<b>2004-2003</b>		
Belt - Serpentine - Alt. & A.C. ....	2271364	▲K080816HD
Belt - Chopper - Rear .....	71388712	C210

②Two Required ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CHALLENGER - Continued</b>		
<b>660 - Continued</b>		
<b>Caterpillar C9 Diesel - Continued</b>		
2004-2003 - Continued		
Belt - Grain Elevator .....	227455M1	C126
Belt - Spreader J.S. ....	227455M1	C126
<b>660B</b>		
<b>Challenger 6-Cyl. 8.4 L Diesel</b>		
2009		
Belt - A.C. ....	71148120	▲9510HD
Belt - Rotary Screen .....	71396754	A68
<b>670</b>		
<b>Caterpillar C9 Diesel</b>		
2008-2006		
Belt - Rotary Screen .....	71396754	A68
Belt - Spreader J.S. ....	227455M1	C126
2005		
Belt - Chopper - Rear .....	71388712	C210
Belt - Rotary Screen .....	71396754	A68
Belt - Spreader J.S. ....	227455M1	C126
2004-2003		
Belt - Chopper - Rear .....	71388712	C210
Belt - Grain Elevator .....	227455M1	C126
Belt - Rotary Screen .....	71396754	A68
Belt - Spreader J.S. ....	227455M1	C126
<b>670B</b>		
<b>Challenger 6-Cyl. 8.4 L Diesel</b>		
2009		
Belt - A.C. ....	71148120	▲9510HD
Belt - Rotary Screen .....	71396754	A68
<b>680B</b>		
<b>Caterpillar C13 Diesel</b>		
2009-2006		
Belt - Rotary Screen .....	71396754	A68
<b>FORD</b>		
<b>611 Combine</b>		
<b>Ford</b>		
1963-1959		
Belt - Fan .....	EAG 8577 A	7380
Belt - W.P. & Gen. ....	EAG 8620 B	7360
<b>622</b>		
<b>Ford 4-Cyl. 256</b>		
1973-1971		
Belt - Fan .....	721305	7695
Belt - Gov. ....		▲9430HD
Belt - W.P. & Gen. ....	721211	▲9540HD
Hose - Upper; Molded Hose .....		20357
Hose - Upper; Strt. Hose .....		24228
Hose - Lower; Molded Hose .....		20357
Hose - Lower; Strt. Hose .....		24228
<b>Ford 4-Cyl. 256 Diesel</b>		
1973-1971		
Belt - Fan .....	721305	7695
Belt - Gov. ....		▲9430HD
Belt - W.P. & Gen. ....	721211	▲9540HD
Hose - Upper; Molded Hose .....		20357
Hose - Upper; Strt. Hose .....		24228
Hose - Lower; Molded Hose .....		20357
Hose - Lower; Strt. Hose .....		24228
<b>642</b>		
<b>Ford 6-Cyl. 380 Diesel</b>		
1979-1971		
Belt - Fan & Alt. ....		▲9470HD
Hose - Upper .....		☞20957
Hose - Lower .....		☞20957
Hose - By Pass .....		24230

Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>642 - Continued</b>		
<b>Ford V-8 361</b>		
1979-1971		
Belt - Fan & Alt. ....	C4TZ 8620 Z	②▲9463HD
Belt - Hyd. Pump .....		▲9490HD
Hose - Upper - Pipe To Rad. ....		24428
Hose - Lower - Eng. To Pipe .....		24432
Hose - Lower - Heat Exch. To Pipe .....		24432
Hose - Lower - Pipe To Heat Exch. ....		☞20206
Hose - Lower - Pipe To Rad. ....		24432
<b>GLENER</b>		
<b>A II</b>		
<b>Allis-Chalmers 6-Cyl. 230</b>		
1967-1964		
Belt - Fan & Gen.; Eng. No. 397016 & Before .....	4510744	▲9470HD
Belt - Fan & Gen.; Eng. No. 397017 Thru 408560 .....	4512419	▲9480HD
Belt - Hyd. Pump; Ser. No. 14053 Thru 26500 .....	1117027	TR28483
Belt - Hyd. Pump; Ser. No. 26501 Thru 30000 .....	1128092	TR28463
<b>A65</b>		
<b>AGCO 6-Cyl. 8.4 L Diesel</b>		
2008		
Belt - Beater Drive .....	71386352	B173
<b>A66</b>		
<b>AGCO 6-Cyl. 8.4 L Diesel</b>		
2009		
Belt - A.C. ....	71148120	▲9510HD
Belt - Rotary Screen .....	71396754	A68
<b>A75</b>		
<b>AGCO 6-Cyl. 8.4 L Diesel</b>		
2008-2007		
Belt - A.C. ....	71148120	▲9510HD
<b>A76</b>		
<b>AGCO 6-Cyl. 8.4 L Diesel</b>		
2009		
Belt - A.C. ....	71148120	▲9510HD
Belt - Rotary Screen .....	71396754	A68
<b>A86</b>		
<b>Caterpillar C13 Diesel</b>		
2009		
Belt - Rotary Screen .....	71396754	A68
<b>B</b>		
<b>Allis-Chalmers 6-Cyl. 230</b>		
1963-1953		
Belt - Fan & Gen.; Eng. No. 397016 & Before .....	4510744	▲9470HD
Belt - Fan & Gen.; Eng. No. 397017 Thru 408560 .....	4512419	▲9480HD
Belt - Hyd. Pump; Ser. No. 14053 Thru 26500 .....	1117027	TR28483
Belt - Hyd. Pump; Ser. No. 26501 Thru 30000 .....	1128092	TR28463
<b>Ford 6-Cyl. 226</b>		
1963-1953		
Hose - Upper .....		●26611
Hose - Lower; Ser. No. 26000 & Before .....		●26611
Hose - Lower; Ser. No. 26001 & After .....		●26612
<b>Hercules 6-Cyl. 237</b>		
1963-1953		
Belt - Fan; Ser. No. 14052 & Before .....	1117027	TR28483
Belt - Hyd. Pump; Ser. No. 13500 & Before ....	1117040	TR28545

②Two Required ☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>B - Continued</b>		
<b>Hercules 6-Cyl. 237 - Continued</b>		
1963-1953 - Continued		
Belt - Hyd. Pump; Ser. No. 13501 Thru 14052	1117027	TR28483
Hose - Upper		●25528
Hose - Lower		●25477
<b>C</b>		
<b>Allis-Chalmers 6-Cyl. 262</b>		
1963-1960		
Belt - Fan & Gen.; Ser. No. 7001 & After	4512419	▲9480HD
Belt - Hyd. Pump	1125973	TR28454
Hose - Upper; W/26 3/8" Rad.		●26611
Hose - Upper; W/31 3/8" Rad.		●26612
Hose - Lower		●26612
<b>C II</b>		
<b>Allis-Chalmers 6-Cyl. 262</b>		
1967-1964		
Belt - Fan & Gen.; Ser. No. 7001 & After	4512419	▲9480HD
<b>CH</b>		
<b>Allis-Chalmers 6-Cyl. 262</b>		
1967-1963		
Belt - Fan & Gen.; Ser. No. 7001 & After	4512419	▲9480HD
Belt - Hyd. Pump	1134651	TR28454
Hose - Upper; W/26 3/8" Rad.		●26611
Hose - Upper; W/31 3/8" Rad.		●26612
Hose - Lower		●26612
<b>CR</b>		
<b>Allis-Chalmers 6-Cyl. 262</b>		
1967-1963		
Belt - Fan & Gen.; Ser. No. 7001 & After	4512419	▲9480HD
Belt - Hyd. Pump	1125973	TR28454
Hose - Upper; W/26 3/8" Rad.		●26611
Hose - Upper; W/31 3/8" Rad.		●26612
Hose - Lower		●26612
<b>Allis-Chalmers 6-Cyl. 262 Diesel</b>		
1967-1963		
Belt - Fan & Gen.; Ser. No. 7001 & After	4512419	▲9480HD
Belt - Hyd. Pump	1125973	TR28454
Hose - Upper; W/26 3/8" Rad.		●26611
Hose - Upper; W/31 3/8" Rad.		●26612
Hose - Lower		●26612
<b>E</b>		
<b>Allis-Chalmers 4-Cyl. 226</b>		
1968-1962		
Belt - Fan	229211	▲9463HD
Belt - Hyd. Pump; W/O P.S.	1130921	▲9447HD
Belt - Hyd. Pump; W/P.S.	1131774	▲9425HD
Hose - Upper		●25476
Hose - Lower		●25477
Hose - By Pass		≧21942
<b>E III</b>		
<b>Allis-Chalmers 6-Cyl. 262</b>		
1968		
Belt - A.C.; W/Comfort Cab	1152788	▲9480HD
Belt - A.C.; W/LaPort Cab	1166813	▲9490HD
Belt - Bin Unloader	1139962	C150
Belt - Conveyor Drive	1139622	C68
Belt - Countershaft	1139965	C83
Belt - Draper Drive; W/2 Rolls	1130442	C73
Belt - Fan & Alt.	1141744	▲9463HD
Belt - Grain Saver & Air Flow	0563619	A98
Belt - Hyd. Pump; W/O P.S.	1142239	▲9451HD
Belt - Hyd. Pump; W/P.S.	1131774	▲9425HD
Belt - Main Drive	1139960	B150
Belt - Reel Drive; W/Long Arms	1118003	C144
Belt - Reel Drive; W/Short Arms; W/Std. Reel	1125977	B124

Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>E III - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 262 - Continued</b>		
1968 - Continued		
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms	0519007	C128
Belt - Reel Drive - Intermediate	1123452	B79
Hose - Upper		●25476
Hose - Lower		●25477
Hose - By Pass		≧21942
<b>F</b>		
<b>Allis-Chalmers 6-Cyl. 262</b>		
1976		
Belt - A.C.	1166813	▲9490HD
Belt - Alt./Gen.	1148119	▲9395HD
Belt - Conveyor Drive	1139622	C68
Belt - Countershaft - PTO	1170678	②7430
Belt - Cyl.; Rice; W/596-908 R.P.M.	1146000	B81
Belt - Cyl.; W/387-590 R.P.M.	1147546	2/B93
Belt - Cyl.; W/907-1383 R.P.M.	1147547	B75
Belt - Gov.	1148120	▲9510HD
Belt - Grain Saver & Air Flow	0563619	A98
Belt - Header; W/Variable Speed Drive	1172514	TR28429
Belt - Hyd. Pump	1148119	▲9395HD
Belt - Main Drive	1183767	B152
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms	1118003	C144
Belt - Reel Drive; W/Std. Drive	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive	1123452	B79
Belt - Traction; W/Hydro. Drive	1147546	2/B93
1975		
Belt - A.C.	1166813	▲9490HD
Belt - Alt./Gen.	1148119	▲9395HD
Belt - Conveyor Drive	1139622	C68
Belt - Countershaft - PTO	1170678	②7430
Belt - Cyl.; Rice; W/596-908 R.P.M.	1146000	B81
Belt - Cyl.; W/387-590 R.P.M.	1147546	2/B93
Belt - Cyl.; W/907-1383 R.P.M.	1147547	B75
Belt - Gov.	1148120	▲9510HD
Belt - Grain Saver & Air Flow	0563619	A98
Belt - Hyd. Pump	1148119	▲9395HD
Belt - Main Drive	1183767	B152
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms	1118003	C144
Belt - Reel Drive; W/Std. Drive	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive	1123452	B79
Belt - Traction; W/Hydro. Drive	1147546	2/B93
1974-1971		
Belt - A.C.	1166813	▲9490HD
Belt - Alt./Gen.	1148119	▲9395HD
Belt - Conveyor Drive	1139622	C68
Belt - Countershaft - PTO	1148119	▲9395HD
Belt - Cyl.; Rice; W/596-908 R.P.M.	1146000	B81
Belt - Cyl.; W/387-590 R.P.M.	1147546	2/B93
Belt - Cyl.; W/907-1383 R.P.M.	1147547	B75
Belt - Gov.	1148120	▲9510HD
Belt - Grain Saver & Air Flow	0563619	A98
Belt - Hyd. Pump	1167408	▲9590HD
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms	1118003	C144
Belt - Reel Drive; W/Std. Drive	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive	1123452	B79
Belt - Traction; W/Hydro. Drive	1147546	2/B93
1970		
Belt - A.C.	1142239	▲9451HD
Belt - Alt./Gen.	1140911	▲9490HD
Belt - Bin Unloader	1139962	C150
Belt - Conveyor Drive	1139622	C68
Belt - Cyl.; W/907-1383 R.P.M.	1147547	B75

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>F - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 262 - Continued</b>		
<b>1970 - Continued</b>		
Belt - Grain Saver & Air Flow .....	0559863	A81
Belt - Main Drive; Rice .....	1139961	2/B148
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Std. Drive .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive .....	1123452	B79
Belt - Traction; W/Hydro. Drive .....	1147546	2/B93
<b>1969</b>		
Belt - A.C. ....	1142239	▲9451HD
Belt - Alt./Gen. ....	1140911	▲9490HD
Belt - Bin Unloader .....	1139962	C150
Belt - Conveyor Drive .....	1139622	C68
Belt - Grain Saver & Air Flow .....	0559863	A81
Belt - Hyd. Pump .....	1133220	TR28483
Belt - Main Drive; Rice .....	1139961	2/B148
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Std. Drive .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive .....	1123452	B79
Belt - Traction - Hydro.; Rice .....	1146744	B92
<b>1968</b>		
Belt - A.C. ....	1142239	▲9451HD
Belt - Alt./Gen. ....	1139189	▲9540HD
Belt - Bin Unloader .....	1139962	C150
Belt - Conveyor Drive .....	1139622	C68
Belt - Countershaft .....	1139965	C83
Belt - Grain Saver & Air Flow .....	0559863	A81
Belt - Hyd. Pump .....	1133220	TR28483
Belt - Main Drive; Rice .....	1139961	2/B148
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Std. Drive .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive .....	1123452	B79
Belt - Traction - Hydro.; Rice .....	1146744	B92
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
<b>1976-1975</b>		
Belt - A.C. ....	1166813	▲9490HD
Belt - Alt./Gen. ....	1154358	▲9540HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Cyl.; Rice; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Gov. ....	1148120	▲9510HD
Belt - Grain Saver & Air Flow .....	1144488	A90
Belt - Hyd. Pump .....	1152609	TR28429
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Std. Drive .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive .....	1123452	B79
Belt - Traction; W/Hydro. Drive .....	1147546	2/B93
Hose - Upper .....		21256
Hose - Lower .....		●26504
<b>1974-1971</b>		
Belt - A.C. ....	1166813	▲9490HD
Belt - Alt./Gen. ....	1154358	▲9540HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Cyl.; Rice; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Gov. ....	1148120	▲9510HD
Belt - Grain Saver & Air Flow .....	1144488	A90
Belt - Hyd. Pump; Rice .....	1152608	TR28445

Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>F - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel - Continued</b>		
<b>1974-1971 - Continued</b>		
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Std. Drive .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive .....	1123452	B79
Belt - Traction; W/Hydro. Drive .....	1147546	2/B93
Hose - Upper .....		21256
Hose - Lower .....		●26504
<b>1970</b>		
Belt - A.C. ....	1142239	▲9451HD
Belt - Alt./Gen. ....	1140911	▲9490HD
Belt - Bin Unloader .....	1139962	C150
Belt - Conveyor Drive .....	1139622	C68
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Hyd. Pump; Rice .....	1152608	TR28445
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Std. Drive .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive .....	1123452	B79
Belt - Traction; W/Hydro. Drive .....	1147546	2/B93
Hose - Upper .....		21256
Hose - Lower .....		●26504
<b>1969</b>		
Belt - A.C. ....	1142239	▲9451HD
Belt - Alt./Gen. ....	1140911	▲9490HD
Belt - Bin Unloader .....	1139962	C150
Belt - Conveyor Drive .....	1139622	C68
Belt - Hyd. Pump; Rice .....	1152608	TR28445
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Std. Drive .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive .....	1123452	B79
Belt - Traction - Hydro.; Rice .....	1146744	B92
Hose - Upper .....		21256
Hose - Lower .....		●26504
<b>1968</b>		
Belt - A.C. ....	1142239	▲9451HD
Belt - Alt./Gen. ....	1139189	▲9540HD
Belt - Bin Unloader .....	1139962	C150
Belt - Conveyor Drive .....	1139622	C68
Belt - Countershaft .....	1139965	C83
Belt - Hyd. Pump; Rice .....	1152608	TR28445
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Std. Drive .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive .....	1123452	B79
Belt - Traction - Hydro.; Rice .....	1146744	B92
Hose - Upper .....		21256
Hose - Lower .....		●26504
<b>Chevrolet 6-Cyl. 292</b>		
<b>1976-1975</b>		
Belt - A.C. ....	1166813	▲9490HD
Belt - Alt./Gen. ....	1148119	▲9395HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Countershaft - PTO .....	1170678	②7430
Belt - Cyl.; Rice; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Gov. ....	1148120	▲9510HD
Belt - Grain Saver & Air Flow .....	0563619	A98
Belt - Hyd. Pump .....	1148119	▲9395HD
Belt - Main Drive .....	1183767	B152
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms .....	1118003	C144

②Two Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>F - Continued</b>		
<b>Chevrolet 6-Cyl. 292 - Continued</b>		
<b>1976-1975 - Continued</b>		
Belt - Reel Drive; W/Std. Drive	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive	1123452	B79
Belt - Traction; W/Hydro. Drive	1147546	2/B93
Hose - Upper	20433	or ●25526
		or <20584
		or ●26612
Hose - Lower		20563
Hose - By Pass		
<b>1974-1971</b>		
Belt - A.C.	1166813	▲9490HD
Belt - Alt./Gen.	1148119	▲9395HD
Belt - Conveyor Drive	1139622	C68
Belt - Countershaft - PTO	1148119	▲9395HD
Belt - Cyl.; Rice; W/596-908 R.P.M.	1146000	B81
Belt - Cyl.; W/387-590 R.P.M.	1147546	2/B93
Belt - Cyl.; W/907-1383 R.P.M.	1147547	B75
Belt - Gov.	1148120	▲9510HD
Belt - Grain Saver & Air Flow	0563619	A98
Belt - Hyd. Pump	1167408	▲9590HD
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms	1118003	C144
Belt - Reel Drive; W/Std. Drive	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive	1123452	B79
Belt - Traction; W/Hydro. Drive	1147546	2/B93
Hose - Upper	20433	or ●25526
		or <20584
		or ●26612
Hose - Lower		20563
Hose - By Pass		
<b>1970</b>		
Belt - A.C.	1142239	▲9451HD
Belt - Alt./Gen.	1140911	▲9490HD
Belt - Bin Unloader	1139962	C150
Belt - Conveyor Drive	1139622	C68
Belt - Cyl.; W/907-1383 R.P.M.	1147547	B75
Belt - Grain Saver & Air Flow	0559863	A81
Belt - Hyd. Pump	1133220	TR28483
Belt - Main Drive; Rice	1139961	2/B148
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms	1118003	C144
Belt - Reel Drive; W/Std. Drive	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive	1123452	B79
Belt - Traction; W/Hydro. Drive	1147546	2/B93
Hose - Lower		●26612
Hose - By Pass		20563
<b>1969</b>		
Belt - A.C.	1142239	▲9451HD
Belt - Alt./Gen.	1140911	▲9490HD
Belt - Bin Unloader	1139962	C150
Belt - Conveyor Drive	1139622	C68
Belt - Grain Saver & Air Flow	0559863	A81
Belt - Hyd. Pump	1133220	TR28483
Belt - Main Drive; Rice	1139961	2/B148
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms	1118003	C144
Belt - Reel Drive; W/Std. Drive	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive	1123452	B79
Belt - Traction - Hydro.; Rice	1146744	B92
Hose - Lower		●26612
Hose - By Pass		20563
<b>1968</b>		
Belt - A.C.	1142239	▲9451HD
Belt - Alt./Gen.	1139189	▲9540HD

Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>F - Continued</b>		
<b>Chevrolet 6-Cyl. 292 - Continued</b>		
<b>1968 - Continued</b>		
Belt - Bin Unloader	1139962	C150
Belt - Conveyor Drive	1139622	C68
Belt - Countershaft	1139965	C83
Belt - Grain Saver & Air Flow	0559863	A81
Belt - Hyd. Pump	1133220	TR28483
Belt - Main Drive; Rice	1139961	2/B148
Belt - Reel Drive; Corn-Soybeans, Rice; W/Long Arms	1118003	C144
Belt - Reel Drive; W/Std. Drive	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms	0519007	C128
Belt - Reel Drive - Intermediate; W/Std. Drive	1123452	B79
Belt - Traction - Hydro.; Rice	1146744	B92
Hose - Lower		●26612
Hose - By Pass		20563
<b>F2</b>		
<b>Allis-Chalmers 4-Cyl. 200 Diesel</b>		
<b>1982</b>		
Belt - A.C.	1193749	▲9510HD
Belt - Alt.	1139187	▲9530HD
Belt - Countershaft - PTO	1300399	②7445
Belt - Cyl.; W/803-1343 R.P.M.	1147547	B75
Belt - Grain Saver & Air Flow; Exc. Field Installed Kit	1190749	A128
Belt - Grain Saver & Air Flow; For Field Installed Kit	1190750	A120
Belt - Header; W/Variable Speed Drive	1172514	TR28429
Belt - Hyd. Pump	1300400	▲9415HD
Belt - Traction; W/Hydro. Drive	1161595	2/B99
Hose - Upper		<21944
		or ●26504
Hose - Lower		●26504
Hose - By Pass		20925
<b>1981-1978</b>		
Belt - A.C.	1193749	▲9510HD
Belt - Alt.	1139187	▲9530HD
Belt - Countershaft - PTO	1300399	②7445
Belt - Cyl.; W/803-1343 R.P.M.	1147547	B75
Belt - Grain Saver & Air Flow; Exc. Field Installed Kit	1190749	A128
Belt - Grain Saver & Air Flow; For Field Installed Kit	1190750	A120
Belt - Hyd. Pump	1300400	▲9415HD
Belt - Traction; W/Hydro. Drive	1147546	2/B93
Hose - Upper		<21944
		or ●26504
Hose - Lower		●26504
Hose - By Pass		20925
<b>1977</b>		
Belt - A.C.	1140911	▲9490HD
Belt - Alt.	1193420	▲9550HD
Belt - Bin Unloader	1194116	C156
Belt - Cyl.; W/803-1343 R.P.M.	1147547	B75
Belt - Grain Saver & Air Flow; For Field Installed Kit	1190750	A120
Belt - Hyd. Pump	1194117	TR28501
Belt - Traction; W/Hydro. Drive	1147546	2/B93
Hose - Lower		●26504
<b>Chevrolet 6-Cyl. 292</b>		
<b>1982</b>		
Belt - A.C.	1140911	▲9490HD
Belt - Alt.	1148119	▲9395HD
Belt - Cyl.; W/803-1343 R.P.M.	1147547	B75
Belt - Gov.	1148120	▲9510HD
Belt - Grain Saver & Air Flow; Exc. Field Installed Kit	1190749	A128
Belt - Grain Saver & Air Flow; For Field Installed Kit	1190750	A120
Belt - Hyd. Pump	1300400	▲9415HD
Belt - Traction; W/Hydro. Drive	1161595	2/B99
Hose - Upper		●25527
Hose - Lower		●26612

②Two Required <Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>F2 - Continued</b>		
<b>Chevrolet 6-Cyl. 292 - Continued</b>		
<b>1982 - Continued</b>		
Hose - By Pass .....		20563
<b>1981-1979</b>		
Belt - A.C. ....	1140911	▲9490HD
Belt - Alt. ....	1148119	▲9395HD
Belt - Countershaft - PTO .....	1300398	②7425
Belt - Cyl.; W/803-1343 R.P.M. ....	1147547	B75
Belt - Gov. ....	1148120	▲9510HD
Belt - Grain Saver & Air Flow; Exc. Field Installed Kit .....	1190749	A128
Belt - Grain Saver & Air Flow; For Field Installed Kit .....	1190750	A120
Belt - Hyd. Pump .....	1300400	▲9415HD
Belt - Hydro. Drive .....	1161595	2/B99
Belt - Main Drive .....	1192495	B158
Belt - Traction; W/Hydro. Drive .....	1147546	2/B93
Hose - Upper .....		●25527
Hose - Lower .....		●26612
Hose - By Pass .....		20563
<b>1978</b>		
Belt - A.C. ....	1140911	▲9490HD
Belt - Alt. ....	1148119	▲9395HD
Belt - Countershaft - PTO .....	1300398	②7425
Belt - Cyl.; W/803-1343 R.P.M. ....	1147547	B75
Belt - Gov. ....	1148120	▲9510HD
Belt - Grain Saver & Air Flow; Exc. Field Installed Kit .....	1190749	A128
Belt - Grain Saver & Air Flow; For Field Installed Kit .....	1190750	A120
Belt - Hyd. Pump .....	1300400	▲9415HD
Belt - Hydro. Drive .....	1161595	2/B99
Belt - Main Drive .....	1192495	B158
Belt - Traction; W/Hydro. Drive .....	1147546	2/B93
Hose - Upper; Ser. No. 39201 & After .....		●25527
Hose - Lower; Ser. No. 39201 & After .....		●26612
Hose - By Pass .....		20563
<b>1977</b>		
Belt - A.C. ....	1140911	▲9490HD
Belt - Alt. ....	1148119	▲9395HD
Belt - Countershaft - PTO .....	1170678	②7430
Belt - Cyl.; W/803-1343 R.P.M. ....	1147547	B75
Belt - Gov. ....	1148120	▲9510HD
Belt - Grain Saver & Air Flow; Exc. Field Installed Kit .....	1190749	A128
Belt - Grain Saver & Air Flow; For Field Installed Kit .....	1190750	A120
Belt - Hyd. Pump .....	1146714	▲9405HD
Belt - Traction; W/Hydro. Drive .....	1147546	2/B93
Hose - By Pass .....		20563
<b>F3</b>		
<b>Allis-Chalmers 4-Cyl. 200 Diesel</b>		
<b>1987</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt. ....	1139187	▲9530HD
Belt - Cyl.; W/803-1343 R.P.M. ....	1147547	B75
Belt - Grain Saver & Air Flow .....	1190749	A128
Belt - Header; W/Variable Speed Drive .....	1172514	TR28429
Belt - Hyd. Pump .....	1141744	▲9463HD
Belt - Traction; W/Hydro. Drive .....	1161595	2/B99
<b>1986-1983</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt. ....	1139187	▲9530HD
Belt - Cyl.; W/803-1343 R.P.M. ....	1147547	B75
Belt - Grain Saver & Air Flow .....	1190749	A128
Belt - Hyd. Pump .....	1141744	▲9463HD
Belt - Traction; W/Hydro. Drive .....	1161595	2/B99
<b>G</b>		
<b>Allis-Chalmers 6-Cyl. 301</b>		
<b>1972-1968</b>		
Belt - A.C.; Ser. No. 12200 & Before .....	1142239	▲9451HD
Belt - A.C.; Ser. No. 12201 Thru 17000 .....	1152788	▲9480HD
Belt - A.C.; Ser. No. 17001 & After .....	1166813	▲9490HD
Belt - Fan & Alt.; Ser. No. 17000 & Before .....	1139187	▲9570HD
Belt - Fan & Alt.; Ser. No. 17001 Thru 21000 .....	1167004	▲9580HD
Belt - Fan & Alt.; Ser. No. 21001 & After .....	1172696	②▲9570HD
Belt - Gov. ....	1164565	7520
Belt - Hyd. Pump; W/43 3/8" Belt O.C. ....	1172514	TR28429
Belt - Hyd. Pump; W/54 1/4" Belt O.C. ....	1154358	▲9540HD

Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>G - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 301 - Continued</b>		
<b>1972-1968 - Continued</b>		
Belt - Fan & Alt.; Ser. No. 17001 & After .....	1165501	②7535
Belt - Gov. ....	1164565	7520
Belt - Hyd. Pump; Ser. No. 21000 & Before .....	1146714	▲9405HD
Belt - Hyd. Pump; Ser. No. 21001 & After .....		▲9540HD
Hose - Upper; Early .....		●26504
Hose - Upper; Late .....		●25532
Hose - Lower; Early .....		●26501
Hose - Lower; Late .....		●26612
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
<b>1973-1968</b>		
Belt - A.C.; Ser. No. 12200 & Before .....	1142239	▲9451HD
Belt - A.C.; Ser. No. 12201 Thru 17000 .....	1152788	▲9480HD
Belt - A.C.; Ser. No. 17001 & After .....		▲9490HD
Belt - Fan & Alt.; Ser. No. 17000 & Before .....	1154797	▲9570HD
Belt - Fan & Alt.; Ser. No. 17001 Thru 21000 .....	1167004	▲9580HD
Belt - Fan & Alt.; Ser. No. 21001 & After .....	1172696	②▲9570HD
Belt - Gov. ....	1164565	7520
Belt - Hyd. Pump; W/43 3/8" Belt O.C. ....	1172514	TR28429
Belt - Hyd. Pump; W/54 1/4" Belt O.C. ....	1154358	▲9540HD
Hose - Upper; Ser. No. 12200 & Before .....		21256
		or ●25527
Hose - Upper; Ser. No. 12201 & After .....		20595
		or ●26505
Hose - Lower .....		●26504
<b>Chevrolet V-8 350</b>		
<b>1972-1968</b>		
Belt - A.C.; Ser. No. 12200 & Before .....	1142239	▲9451HD
Belt - A.C.; Ser. No. 12201 Thru 17000 .....	1152788	▲9480HD
Belt - A.C.; Ser. No. 17001 & After .....	1166813	▲9490HD
Belt - Fan & Alt.; Ser. No. 17000 & Before .....	1139187	▲9530HD
Belt - Fan & Alt.; Ser. No. 17001 & After .....	1165501	②7535
Belt - Gov. ....	1164565	7520
Belt - Hyd. Pump; Ser. No. 21000 & Before .....	1146714	▲9405HD
Belt - Hyd. Pump; Ser. No. 21001 & After .....		▲9540HD
Hose - Upper .....		●25530
<b>GH</b>		
<b>Allis-Chalmers 6-Cyl. 301</b>		
<b>1972-1969</b>		
Belt - A.C.; Ser. No. 12200 & Before .....	1142239	▲9451HD
Belt - A.C.; Ser. No. 12201 Thru 17000 .....	1152788	▲9480HD
Belt - A.C.; Ser. No. 17001 & After .....	1166813	▲9490HD
Belt - Fan & Alt.; Ser. No. 17000 & Before .....	1139187	▲9530HD
Belt - Fan & Alt.; Ser. No. 17001 & After .....	1165501	②7535
Belt - Gov. ....	1164565	7520
Belt - Hyd. Pump; Ser. No. 21000 & Before .....	1146714	▲9405HD
Belt - Hyd. Pump; Ser. No. 21001 & After .....		▲9540HD
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
<b>1972-1969</b>		
Belt - A.C.; Ser. No. 12200 & Before .....	1142239	▲9451HD
Belt - A.C.; Ser. No. 12201 Thru 17000 .....	1152788	▲9480HD
Belt - A.C.; Ser. No. 17001 & After .....	1166813	▲9490HD
Belt - Fan & Alt.; Ser. No. 17000 & Before .....	1154797	▲9570HD
Belt - Fan & Alt.; Ser. No. 17001 Thru 21000 .....	1167004	▲9580HD
Belt - Fan & Alt.; Ser. No. 21001 & After .....	1172696	②▲9570HD
Belt - Gov. ....	1164565	7520
Belt - Hyd. Pump; W/43 3/8" Belt O.C. ....	1172514	TR28429
Belt - Hyd. Pump; W/54 1/4" Belt O.C. ....	1154358	▲9540HD
<b>K</b>		
<b>Chevrolet 6-Cyl. 250</b>		
<b>1976</b>		
Belt - A.C.; W/LaPort Cab .....	1166813	▲9490HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Countershaft - PTO .....	1170283	②7440
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Draper Drive; W/2 Rolls .....	1130442	C73
Belt - Fan & Alt. ....	1146660	7400
Belt - Gov. ....	1146702	7480
Belt - Grain Saver & Air Flow .....	0563619	A98

②Two Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>K - Continued</b>		
<b>Chevrolet 6-Cyl. 250 - Continued</b>		
<b>1976 - Continued</b>		
Belt - Header; W/Variable Speed Drive .....	1172514	TR28429
Belt - Hyd. Pump; W/O P.S. ....	1142239	▲9451HD
Belt - Hyd. Pump; W/P.S. ....	1166813	▲9490HD
Belt - Reel Drive; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Short Arms; W/Std. Reel .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate .....	1123452	B79
<b>1975-1973</b>		
Belt - A.C.; W/LaPort Cab .....	1166813	▲9490HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Countershaft - PTO .....	1170283	②7440
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Draper Drive; W/2 Rolls .....	1130442	C73
Belt - Fan & Alt. ....	1146660	7400
Belt - Gov. ....	1146702	7480
Belt - Grain Saver & Air Flow .....	0563619	A98
Belt - Hyd. Pump; W/O P.S. ....	1142239	▲9451HD
Belt - Hyd. Pump; W/P.S. ....	1166813	▲9490HD
Belt - Reel Drive; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Short Arms; W/Std. Reel .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate .....	1123452	B79
<b>1972</b>		
Belt - A.C.; W/Comfort Cab .....	1152788	▲9480HD
Belt - A.C.; W/LaPort Cab .....	1166813	▲9490HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Countershaft - PTO .....	1170283	②7440
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Draper Drive; W/2 Rolls .....	1130442	C73
Belt - Fan & Alt. ....	1146660	7400
Belt - Gov. ....	1146702	7480
Belt - Grain Saver & Air Flow .....	0563619	A98
Belt - Hyd. Pump; W/O P.S. ....	1142239	▲9451HD
Belt - Hyd. Pump; W/P.S. ....	1166813	▲9490HD
Belt - Reel Drive; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Short Arms; W/Std. Reel .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate .....	1123452	B79
<b>1971-1970</b>		
Belt - A.C.; W/Comfort Cab .....	1152788	▲9480HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Countershaft - PTO; W/39 7/8" Belt O.C. ....	1148119	▲9395HD
Belt - Countershaft - PTO; W/44 5/8" Belt O.C. ....	1170283	②7440
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Draper Drive; W/2 Rolls .....	1130442	C73
Belt - Fan & Alt. ....	1146660	7400
Belt - Gov. ....	1146702	7480
Belt - Grain Saver & Air Flow .....	0563619	A98
Belt - Hyd. Pump; W/O P.S. ....	1152615	▲9660HD
Belt - Hyd. Pump; W/P.S. ....	1146713	▲9620HD
Belt - Main Drive .....	1139961	2/B148
Belt - Reel Drive; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Short Arms; W/Std. Reel .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate .....	1123452	B79
<b>1969-1968</b>		
Belt - A.C.; W/Stolper Cab .....	1142239	▲9451HD
Belt - Conveyor Drive .....	1139622	C68

Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>K - Continued</b>		
<b>Chevrolet 6-Cyl. 250 - Continued</b>		
<b>1969-1968 - Continued</b>		
Belt - Countershaft - PTO; W/39 7/8" Belt O.C. ....	1148119	▲9395HD
Belt - Countershaft - PTO; W/44 5/8" Belt O.C. ....	1170283	②7440
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/596-908 R.P.M. ....	1146000	B81
Belt - Draper Drive; W/2 Rolls .....	1130442	C73
Belt - Fan & Alt. ....	1146660	7400
Belt - Gov. ....	1146702	7480
Belt - Grain Saver & Air Flow .....	0563619	A98
Belt - Hyd. Pump; W/O P.S. ....	1152615	▲9660HD
Belt - Hyd. Pump; W/P.S. ....	1146713	▲9620HD
Belt - Main Drive .....	1139961	2/B148
Belt - Reel Drive; W/Long Arms .....	1118003	C144
Belt - Reel Drive; W/Short Arms; W/Std. Reel .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/Long Arms .....	0519007	C128
Belt - Reel Drive - Intermediate .....	1123452	B79
<b>K2</b>		
<b>Allis-Chalmers 4-Cyl. 200 Diesel</b>		
<b>1982</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt. ....	1139187	▲9530HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Countershaft - PTO .....	1300399	②7445
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Draper Drive; W/2 Rolls .....	1130442	C73
Belt - Header; W/Variable Speed Drive .....	1172514	TR28429
Belt - Hyd. Pump .....	1300400	▲9415HD
Belt - Reel Drive; W/Short Arms; W/Std. Reel .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/H.D. Reel .....	1118003	C144
Belt - Reel Drive - Intermediate .....	1123452	B79
Belt - Spreader .....	1308584	B195
Hose - Upper .....		⊘-21944
<b>1981-1978</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt. ....	1139187	▲9530HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Countershaft - PTO .....	1300399	②7445
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Draper Drive; W/2 Rolls .....	1130442	C73
Belt - Hyd. Pump .....	1300400	▲9415HD
Belt - Reel Drive; W/Short Arms; W/Std. Reel .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/H.D. Reel .....	1118003	C144
Belt - Reel Drive - Intermediate .....	1123452	B79
Belt - Spreader .....	1308584	B195
Hose - Upper .....		⊘-21944
<b>1977</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt. ....	1139187	▲9530HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Countershaft - PTO .....	1300399	②7445
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Draper Drive; W/2 Rolls .....	1130442	C73
Belt - Hyd. Pump .....	1146714	▲9405HD
Belt - Reel Drive; W/Short Arms; W/Std. Reel .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/H.D. Reel .....	1118003	C144
Belt - Reel Drive - Intermediate .....	1123452	B79
Hose - Upper .....		⊘-21944

②Two Required ⊘Cut to Fit ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>K2 - Continued</b>		
<b>Chevrolet 6-Cyl. 250</b>		
1981-1978		
Belt - A.C. ....	1140911	▲9490HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Draper Drive; W/2 Rolls .....	1130442	C73
Belt - Fan & Alt. ....	1146660	7400
Belt - Gov. ....	1146702	7480
Belt - Grain Saver & Air Flow .....	1190749	A128
Belt - Hyd. Pump .....	1300400	▲9415HD
Belt - Reel Drive; W/Short Arms; W/Std. Reel .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/H.D. Reel .....	1118003	C144
Belt - Reel Drive - Intermediate .....	1123452	B79
Belt - Spreader .....	1308584	B195
Hose - Upper .....	20433	or ●25526
		or ●20584
		or ●26612
Hose - Lower .....		
1977		
Belt - A.C. ....	1140911	▲9490HD
Belt - Conveyor Drive .....	1139622	C68
Belt - Countershaft - PTO .....	1170678	②7430
Belt - Cyl.; W/387-590 R.P.M. ....	1147546	2/B93
Belt - Cyl.; W/596-908 R.P.M. ....	1146000	B81
Belt - Cyl.; W/907-1383 R.P.M. ....	1147547	B75
Belt - Draper Drive; W/2 Rolls .....	1130442	C73
Belt - Fan & Alt. ....	1146660	7400
Belt - Gov. ....	1146702	7480
Belt - Grain Saver & Air Flow .....	1190749	A128
Belt - Hyd. Pump .....	1146714	▲9405HD
Belt - Reel Drive; W/Short Arms; W/Std. Reel .....	1125977	B124
Belt - Reel Drive; W/Variable Speed Drive; W/H.D. Reel .....	1118003	C144
Belt - Reel Drive - Intermediate .....	1123452	B79
Hose - Upper .....	20433	or ●25526
		or ●20584
		or ●26612
Hose - Lower .....		
<b>L</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
1976		
Belt - A.C. ....	1166813	▲9490HD
Belt - Alt.; W/Single Alt. ....	1159298	②▲9580HD
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	▲9625HD
Belt - Alt. - Upper; W/Dual Alts. ....	1167004	▲9580HD
Belt - Bin Unloader .....	1187728	C105
Belt - Cyl.; W/639-1036 R.P.M. ....	1161595	2/B99
Belt - Grain Saver & Air Flow - Upper .....	1178329	B162
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ...	1173232	▲9640HD
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	②▲9620HD
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1173472	C345
1975-1974		
Belt - A.C. ....	1166813	▲9490HD
Belt - Alt.; W/Single Alt. ....	1159298	②▲9580HD
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	▲9625HD
Belt - Alt. - Upper; W/Dual Alts. ....	1167004	▲9580HD
Belt - Cyl.; W/639-1036 R.P.M. ....	1161595	2/B99
Belt - Grain Saver & Air Flow - Upper .....	1178329	B162
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ...	1173232	▲9640HD
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	②▲9620HD
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1173472	C345
1973		
Belt - A.C. ....	1166813	▲9490HD
Belt - Alt.; W/Single Alt. ....	1172696	②▲9570HD
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	▲9625HD
Belt - Alt. - Upper; W/Dual Alts. ....	1167004	▲9580HD
Belt - Cyl.; W/639-1036 R.P.M. ....	1161595	2/B99
Belt - Grain Saver & Air Flow - Upper .....	1178329	B162
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ...	1173232	▲9640HD

Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>L - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel - Continued</b>		
1973 - Continued		
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	②▲9620HD
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1173472	C345
1972		
Belt - A.C. ....	1166813	▲9490HD
Belt - Alt.; W/Single Alt. ....	1172696	②▲9570HD
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	▲9625HD
Belt - Alt. - Upper; W/Dual Alts. ....	1167004	▲9580HD
Belt - Cyl.; W/639-1036 R.P.M. ....	1161595	2/B99
Belt - Grain Saver & Air Flow - Upper .....	1178329	B162
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ...	1173232	▲9640HD
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	②▲9620HD
Belt - Separator Fan .....	1176312	A74
Belt - Straw Chopper .....	1173472	C345
<b>Chevrolet V-8 350</b>		
1976		
Belt - A.C. ....	1166813	▲9490HD
Belt - Alt. ....	1175751	②7550
Belt - Bin Unloader .....	1187728	C105
Belt - Cyl.; W/639-1036 R.P.M. ....	1161595	2/B99
Belt - Gov. ....	1164565	7520
Belt - Grain Saver & Air Flow - Upper .....	1178329	B162
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ...	1172977	▲9680HD
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	②▲9620HD
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1173472	C345
Hose - By Pass .....		20566
1975-1973		
Belt - A.C. ....	1166813	▲9490HD
Belt - Alt. ....	1175751	②7550
Belt - Cyl.; W/639-1036 R.P.M. ....	1161595	2/B99
Belt - Gov. ....	1164565	7520
Belt - Grain Saver & Air Flow - Upper .....	1178329	B162
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ...	1172977	▲9680HD
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	②▲9620HD
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1173472	C345
Hose - By Pass .....		20566
1972		
Belt - A.C. ....	1166813	▲9490HD
Belt - Alt. ....	1165501	②7535
Belt - Cyl.; W/639-1036 R.P.M. ....	1161595	2/B99
Belt - Gov. ....	1164565	7520
Belt - Grain Saver & Air Flow - Upper .....	1178329	B162
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ...	1172977	▲9680HD
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	②▲9620HD
Belt - Separator Fan .....	1176312	A74
Belt - Straw Chopper .....	1173472	C345
Hose - By Pass .....		20566
<b>L2</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
1982		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/H.D. Alt. ....	1303453	②▲9630HD
Belt - Alt.; W/Single Alt. ....	1193733	②▲9550HD
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	▲9625HD
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	▲9550HD
Belt - Bin Unloader .....	1187728	C105
Belt - Cyl.; W/804-1318 R.P.M. ....	1188635	②B114
Belt - Grain Saver & Air Flow - Lower .....	1300867	C190
Belt - Grain Saver & Air Flow - Upper .....	1306291	A110
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1317254	▲9640HD
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1300867	C190
Hose - Lower; W/Hydro. Drive .....		≈21194
Hose - By Pass .....		≈21942
1981-1980		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/H.D. Alt. ....	1303453	②▲9630HD
Belt - Alt.; W/Single Alt. ....	1193733	②▲9550HD
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	▲9625HD
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	▲9550HD

②Two Required ≈Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>L2 - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel - Continued</b>		
<b>1981-1980 - Continued</b>		
Belt - Bin Unloader .....	1187728	C105
Belt - Cyl.; W/804-1318 R.P.M. ....	1188635	②B114
Belt - Grain Saver & Air Flow - Lower .....	1300867	C190
Belt - Grain Saver & Air Flow - Upper .....	1306291	A110
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1317254	▲9640HD
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1300867	C190
Hose - Lower; W/Hydro. Drive .....	✗21194	
Hose - Lower; W/Man. Trans. ....	●26524	
Hose - By Pass .....	✗21942	
<b>1979</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/H.D. Alt. ....	1303453	②▲9630HD
Belt - Alt.; W/Single Alt. ....	1193733	②▲9550HD
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	▲9625HD
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	▲9550HD
Belt - Bin Unloader .....	1187728	C105
Belt - Cyl.; W/804-1318 R.P.M. ....	1188635	②B114
Belt - Grain Saver & Air Flow - Lower .....	1300867	C190
Belt - Grain Saver & Air Flow - Upper .....	1306291	A110
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1300867	C190
Hose - Lower .....	●26521	
Hose - By Pass .....	✗21942	
<b>1978-1977</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/H.D. Alt. ....	1303453	②▲9630HD
Belt - Alt.; W/Single Alt. ....	1193733	②▲9550HD
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	▲9625HD
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	▲9550HD
Belt - Bin Unloader .....	1187728	C105
Belt - Cyl.; W/639-1036 R.P.M. ....	1161595	2/B99
Belt - Cyl.; W/804-1318 R.P.M. ....	1147546	2/B93
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1173472	C345
Hose - Lower .....	●26521	
Hose - By Pass .....	✗21942	
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
<b>1982-1980</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/105A. Alt. ....	1181482	②TR22676
Belt - Alt.; W/110A. H.D. Alt. ....	1195451	②TR22711
Belt - Alt. - Lower; W/Dual Alts. ....	1184961	TR22692
Belt - Alt. - Upper; W/Dual Alts. ....	1186454	TR22676
Belt - Bin Unloader .....	1187728	C105
Belt - Cyl.; W/804-1318 R.P.M. ....	1188635	②B114
Belt - Grain Saver & Air Flow - Lower .....	1300867	C190
Belt - Grain Saver & Air Flow - Upper .....	1306291	A110
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1317254	▲9640HD
Belt - Hydro. Drive .....	1188636	③B114
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1300867	C190
Hose - Upper .....	●26505	
Hose - Lower; W/Hydro. Drive .....	✗21194	
<b>1979</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/105A. Alt. ....	1181482	②TR22676
Belt - Alt.; W/110A. H.D. Alt. ....	1195451	②TR22711
Belt - Alt. - Lower; W/Dual Alts. ....	1184961	TR22692
Belt - Alt. - Upper; W/Dual Alts. ....	1186454	TR22676
Belt - Bin Unloader .....	1187728	C105
Belt - Cyl.; W/804-1318 R.P.M. ....	1188635	②B114
Belt - Grain Saver & Air Flow - Lower .....	1300867	C190
Belt - Grain Saver & Air Flow - Upper .....	1306291	A110
Belt - Hyd. Pump .....	1175687	▲9620HD
Belt - Hydro. Drive .....	1188636	③B114
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1300867	C190
Hose - Lower .....	●26521	
<b>1978</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/105A. Alt. ....	1181482	②TR22676
Belt - Alt.; W/110A. H.D. Alt. ....	1195451	②TR22711
Belt - Alt. - Lower; W/Dual Alts. ....	1184961	TR22692

Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>L2 - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel - Continued</b>		
<b>1978 - Continued</b>		
Belt - Alt. - Upper; W/Dual Alts. ....	1186454	TR22676
Belt - Bin Unloader .....	1187728	C105
Belt - Cyl.; W/639-1036 R.P.M. ....	1161595	2/B99
Belt - Cyl.; W/804-1318 R.P.M. ....	1147546	2/B93
Belt - Hyd. Pump .....	1175687	▲9620HD
Belt - Hydro. Drive .....	1188636	③B114
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1173472	C345
Hose - Lower .....	●26521	
<b>1977</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/105A. Alt. ....	1181482	②TR22676
Belt - Alt.; W/110A. H.D. Alt. ....	1195451	②TR22711
Belt - Alt. - Lower; W/Dual Alts. ....	1184961	TR22692
Belt - Alt. - Upper; W/Dual Alts. ....	1186454	TR22676
Belt - Bin Unloader .....	1187728	C105
Belt - Cyl.; W/639-1036 R.P.M. ....	1161595	2/B99
Belt - Cyl.; W/804-1318 R.P.M. ....	1147546	2/B93
Belt - Hyd. Pump .....	1175687	▲9620HD
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1173472	C345
Hose - Lower .....	●26521	
<b>L3</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
<b>1987-1984</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/H.D. Alt. ....	1303453	②▲9630HD
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	▲9625HD
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	▲9550HD
Belt - Bin Unloader .....	1187728	C105
Belt - Grain Saver & Air Flow - Lower .....	1300867	C190
Belt - Grain Saver & Air Flow - Upper .....	1306291	A110
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1317254	▲9640HD
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1300867	C190
<b>1983</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/H.D. Alt. ....	1303453	②▲9630HD
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	▲9625HD
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	▲9550HD
Belt - Bin Unloader .....	1187728	C105
Belt - Cyl.; W/804-1318 R.P.M.; Ser. No. 26115 & Before .....	1188635	②B114
Belt - Grain Saver & Air Flow - Lower .....	1300867	C190
Belt - Grain Saver & Air Flow - Upper .....	1306291	A110
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1317254	▲9640HD
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1300867	C190
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
<b>1987-1985</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/105A. Alt. ....	1181482	②TR22676
Belt - Alt.; W/110A. H.D. Alt. ....	1195451	②TR22711
Belt - Alt. - Lower; W/Dual Alts. ....	1184961	TR22692
Belt - Alt. - Upper; W/Dual Alts. ....	1186454	TR22676
Belt - Bin Unloader .....	1187728	C105
Belt - Grain Saver & Air Flow - Lower .....	1300867	C190
Belt - Grain Saver & Air Flow - Upper .....	1306291	A110
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1317254	▲9640HD
Belt - Separator Fan .....	1176492	B73
Belt - Straw Chopper .....	1300867	C190
<b>1984</b>		
Belt - A.C. ....	1193749	▲9510HD
Belt - Alt.; W/105A. Alt. ....	1181482	②TR22676
Belt - Alt.; W/110A. H.D. Alt. ....	1195451	②TR22711
Belt - Alt. - Lower; W/Dual Alts. ....	1184961	TR22692
Belt - Alt. - Upper; W/Dual Alts. ....	1186454	TR22676
Belt - Bin Unloader .....	1187728	C105
Belt - Grain Saver & Air Flow - Lower .....	1300867	C190
Belt - Grain Saver & Air Flow - Upper .....	1306291	A110
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1317254	▲9640HD
Belt - Hydro. Drive; Ser. No. 15501 Thru 28349 .....	1188636	③B114

②Two Required ③Three Required ✗Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>L3 - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel - Continued</b>		
<b>1984 - Continued</b>		
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1300867	<b>C190</b>
<b>1983</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt.; W/105A. Alt. ....	1181482	<b>②TR22676</b>
Belt - Alt.; W/110A. H.D. Alt. ....	1195451	<b>②TR22711</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184961	<b>TR22692</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1186454	<b>TR22676</b>
Belt - Bin Unloader .....	1187728	<b>C105</b>
Belt - Cyl.; W/804-1318 R.P.M.; Ser. No. 26115 & Before .....	1188635	<b>②B114</b>
Belt - Grain Saver & Air Flow - Lower .....	1300867	<b>C190</b>
Belt - Grain Saver & Air Flow - Upper .....	1306291	<b>A110</b>
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1317254	<b>▲9640HD</b>
Belt - Hydro. Drive .....	1188636	<b>③B114</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1300867	<b>C190</b>
<b>M</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
<b>1976</b>		
Belt - A.C. ....	1166813	<b>▲9490HD</b>
Belt - Alt.; W/Single Alt. ....	1159298	<b>②▲9580HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1167004	<b>▲9580HD</b>
Belt - Bin Unloader .....	1187728	<b>C105</b>
Belt - Cyl.; W/639-1046 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/804-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Grain Saver & Air Flow - Upper .....	1178329	<b>B162</b>
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ....	1173232	<b>▲9640HD</b>
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	<b>②▲9620HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1173472	<b>C345</b>
Hose - Lower; W/Hydro. Drive .....		<b>●26506</b>
Hose - By Pass .....		<b>20566</b>
<b>1975</b>		
Belt - A.C. ....	1166813	<b>▲9490HD</b>
Belt - Alt.; W/Single Alt. ....	1159298	<b>②▲9580HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1167004	<b>▲9580HD</b>
Belt - Cyl.; W/639-1046 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/804-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Grain Saver & Air Flow - Upper .....	1178329	<b>B162</b>
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ....	1173232	<b>▲9640HD</b>
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	<b>②▲9620HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1300867	<b>C190</b>
Hose - Lower; W/Hydro. Drive .....		<b>●26506</b>
Hose - By Pass .....		<b>20566</b>
<b>1974</b>		
Belt - A.C. ....	1166813	<b>▲9490HD</b>
Belt - Alt.; W/Single Alt. ....	1159298	<b>②▲9580HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1167004	<b>▲9580HD</b>
Belt - Cyl.; W/639-1046 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/804-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Grain Saver & Air Flow - Upper .....	1178329	<b>B162</b>
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ....	1173232	<b>▲9640HD</b>
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	<b>②▲9620HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1300867	<b>C190</b>
Hose - By Pass .....		<b>20566</b>
<b>1973</b>		
Belt - A.C. ....	1166813	<b>▲9490HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1167004	<b>▲9580HD</b>
Belt - Cyl.; W/639-1046 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/804-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Grain Saver & Air Flow - Upper .....	1178329	<b>B162</b>
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ....	1173232	<b>▲9640HD</b>
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	<b>②▲9620HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1300867	<b>C190</b>
Hose - By Pass .....		<b>20566</b>

Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>M - Continued</b>		
<b>Chevrolet V-8 350</b>		
<b>1976</b>		
Belt - A.C. ....	1166813	<b>▲9490HD</b>
Belt - Alt. ....	1165501	<b>②7535</b>
Belt - Bin Unloader .....	1187728	<b>C105</b>
Belt - Cyl.; W/639-1046 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/804-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Grain Saver & Air Flow - Upper .....	1178329	<b>B162</b>
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ....	1172977	<b>▲9680HD</b>
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175686	<b>▲9650HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Hose - By Pass .....		<b>20566</b>
<b>1975-1973</b>		
Belt - A.C. ....	1166813	<b>▲9490HD</b>
Belt - Alt. ....	1165501	<b>②7535</b>
Belt - Cyl.; W/639-1046 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/804-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Grain Saver & Air Flow - Upper .....	1178329	<b>B162</b>
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ....	1172977	<b>▲9680HD</b>
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175686	<b>▲9650HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Hose - By Pass .....		<b>20566</b>
<b>M2</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
<b>1982-1981</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt.; W/Single Alt. ....	1193733	<b>②▲9550HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	<b>▲9550HD</b>
Belt - Cyl.; W/639-1046 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/803-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Cyl.; W/804-1318 R.P.M. ....	1188635	<b>②B114</b>
Belt - Grain Saver & Air Flow - Upper .....	1306291	<b>A110</b>
Belt - Hyd. Pump .....	1317254	<b>▲9640HD</b>
Belt - Hydro. Drive .....	1188635	<b>②B114</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1173472	<b>C345</b>
Hose - Lower .....		<b>●26524</b>
Hose - By Pass .....		<b>≠21942</b>
<b>1980-1979</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt.; W/Single Alt. ....	1193733	<b>②▲9550HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	<b>▲9550HD</b>
Belt - Cyl.; W/639-1046 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/803-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Cyl.; W/804-1318 R.P.M. ....	1188635	<b>②B114</b>
Belt - Grain Saver & Air Flow - Upper .....	1306291	<b>A110</b>
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ....	1173232	<b>▲9640HD</b>
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	<b>②▲9620HD</b>
Belt - Hydro. Drive .....	1188635	<b>②B114</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1173472	<b>C345</b>
Hose - Lower .....		<b>●26524</b>
Hose - By Pass .....		<b>≠21942</b>
<b>1978</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt.; W/Single Alt. ....	1193733	<b>②▲9550HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	<b>▲9550HD</b>
Belt - Cyl.; W/639-1046 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/803-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ....	1173232	<b>▲9640HD</b>
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	<b>②▲9620HD</b>
Belt - Hydro. Drive .....	1188635	<b>②B114</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Hose - Lower .....		<b>●26524</b>
Hose - By Pass .....		<b>≠21942</b>
<b>1977</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt.; W/Single Alt. ....	1193733	<b>②▲9550HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	<b>▲9550HD</b>
Belt - Bin Unloader .....	1187728	<b>C105</b>

②Two Required ③Three Required ≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>M2 - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel - Continued</b>		
<b>1977 - Continued</b>		
Belt - Countershaft - Thresher Pivot To Center Shaft .....	1179490	<b>B122</b>
Belt - Cyl.; W/639-1046 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/803-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Hyd. Pump; W/2 1/2" Header Lift Cyl. ...	1173232	<b>▲9640HD</b>
Belt - Hyd. Pump; W/3" Header Lift Cyl. ....	1175687	<b>②▲9620HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1173472	<b>C345</b>
Hose - Lower .....		<b>●26524</b>
Hose - By Pass .....		<b>≧&lt;21942</b>
<b>M3</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
<b>1988-1985</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	<b>▲9550HD</b>
Belt - Grain Saver & Air Flow - Lower; W/O Chopper .....	1300867	<b>C190</b>
Belt - Hyd. Pump .....	1317254	<b>▲9640HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1300867	<b>C190</b>
<b>1984</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	<b>▲9550HD</b>
Belt - Grain Saver & Air Flow - Lower; W/O Chopper .....	1300867	<b>C190</b>
Belt - Hyd. Pump .....	1317254	<b>▲9640HD</b>
Belt - Hydro. Drive; Ser. No. 18401 Thru 26300 .....	1188635	<b>②B114</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1300867	<b>C190</b>
<b>1983</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	<b>▲9550HD</b>
Belt - Grain Saver & Air Flow - Lower; W/O Chopper .....	1300867	<b>C190</b>
Belt - Hyd. Pump .....	1317254	<b>▲9640HD</b>
Belt - Hydro. Drive .....	1188635	<b>②B114</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1300867	<b>C190</b>
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
<b>1985</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	<b>▲9550HD</b>
Belt - Grain Saver & Air Flow - Lower; W/O Chopper .....	1300867	<b>C190</b>
Belt - Hyd. Pump .....	1317254	<b>▲9640HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1300867	<b>C190</b>
<b>1984</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1193420	<b>▲9550HD</b>
Belt - Grain Saver & Air Flow - Lower; W/O Chopper .....	1300867	<b>C190</b>
Belt - Hyd. Pump .....	1317254	<b>▲9640HD</b>
Belt - Hydro. Drive; Ser. No. 18401 Thru 26300 .....	1188635	<b>②B114</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1300867	<b>C190</b>
<b>MH Hillside</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
<b>1976</b>		
Belt - A.C. ....	1166813	<b>▲9490HD</b>
Belt - Alt.; W/H.D. Alt. ....	1195451	<b>②TR22711</b>
Belt - Alt.; W/Single Alt. ....	1159298	<b>②▲9580HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1167004	<b>▲9580HD</b>

Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>MH Hillside - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel - Continued</b>		
<b>1976 - Continued</b>		
Belt - Bin Unloader .....	1187728	<b>C105</b>
Belt - Countershaft - Swivel .....	1192282	<b>C87</b>
Belt - Countershaft - Thresher Pivot To Center Shaft .....	1179490	<b>②B122</b>
Belt - Cyl.; W/412-1343 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/633-1059 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/803-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Hyd. Pump .....	1327638	<b>②▲9605HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1173472	<b>C345</b>
Belt - Traction - Hydro. ....	1188635	<b>B114</b>
<b>1975-1974</b>		
Belt - A.C. ....	1166813	<b>▲9490HD</b>
Belt - Alt.; W/Single Alt. ....	1159298	<b>②▲9580HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1167004	<b>▲9580HD</b>
Belt - Countershaft - Swivel .....	1192282	<b>C87</b>
Belt - Countershaft - Thresher Pivot To Center Shaft .....	1179490	<b>②B122</b>
Belt - Cyl.; W/412-1343 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/633-1059 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/803-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Hyd. Pump .....	1327638	<b>②▲9605HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1173472	<b>C345</b>
<b>1973</b>		
Belt - A.C. ....	1166813	<b>▲9490HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Alt. - Upper; W/Dual Alts. ....	1167004	<b>▲9580HD</b>
Belt - Countershaft - Swivel .....	1192282	<b>C87</b>
Belt - Countershaft - Thresher Pivot To Center Shaft .....	1179490	<b>②B122</b>
Belt - Cyl.; W/412-1343 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/633-1059 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/803-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Hyd. Pump .....	1327638	<b>②▲9605HD</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1173472	<b>C345</b>
<b>MH2 Hillside</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
<b>1982-1979</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt.; W/H.D. Alt. ....	1195451	<b>②TR22711</b>
Belt - Alt.; W/Single Alt. ....	1193733	<b>②▲9550HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Bin Unloader .....	1187728	<b>C105</b>
Belt - Countershaft - Swivel .....	1192282	<b>C87</b>
Belt - Countershaft - Thresher Pivot To Center Shaft .....	1179490	<b>②B122</b>
Belt - Cyl.; W/804-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Hyd. Pump .....	1327638	<b>②▲9605HD</b>
Belt - Hydro. Drive .....	1188635	<b>②B114</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1300867	<b>C190</b>
<b>1978-1977</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>
Belt - Alt.; W/H.D. Alt. ....	1195451	<b>②TR22711</b>
Belt - Alt.; W/Single Alt. ....	1193733	<b>②▲9550HD</b>
Belt - Alt. - Lower; W/Dual Alts. ....	1184327	<b>▲9625HD</b>
Belt - Bin Unloader .....	1187728	<b>C105</b>
Belt - Countershaft - Swivel .....	1192282	<b>C87</b>
Belt - Countershaft - Thresher Pivot To Center Shaft .....	1179490	<b>②B122</b>
Belt - Cyl.; W/412-1343 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/633-1059 R.P.M. ....	1161595	<b>2/B99</b>
Belt - Cyl.; W/804-1343 R.P.M. ....	1147546	<b>2/B93</b>
Belt - Hyd. Pump .....	1327638	<b>②▲9605HD</b>
Belt - Hydro. Drive .....	1188635	<b>②B114</b>
Belt - Separator Fan .....	1176492	<b>B73</b>
Belt - Straw Chopper .....	1173472	<b>C345</b>
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
<b>1982-1979</b>		
Belt - A.C. ....	1193749	<b>▲9510HD</b>

②Two Required ≧<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>MH2 Hillside - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel - Continued</b>		
<b>1982-1979 - Continued</b>		
Belt - Alt.; W/H.D. Alt.	1195451	②TR22711
Belt - Alt.; W/Single Alt.	1181482	②TR22676
Belt - Alt. - Lower; W/Dual Alts.	1184961	TR22692
Belt - Alt. - Upper; W/Dual Alts.	1186454	TR22676
Belt - Bin Unloader	1187728	C105
Belt - Countershaft - Swivel	1192282	C87
Belt - Countershaft - Thresher Pivot To Center Shaft	1179490	②B122
Belt - Cyl.; W/804-1343 R.P.M.	1147546	2/B93
Belt - Hyd. Pump	1327638	②▲9605HD
Belt - Hydro. Drive	1188636	③B114
Belt - Separator Fan	1176492	B73
Belt - Straw Chopper	1300867	C190
Hose - Lower; W/Hydro. Drive; Ser. No. 19500 & Before		●26524
Hose - Lower; W/Hydro. Drive; Ser. No. 19501 & After		⊖21194
<b>1978-1977</b>		
Belt - A.C.	1193749	▲9510HD
Belt - Alt.; W/H.D. Alt.	1195451	②TR22711
Belt - Alt.; W/Single Alt.	1181482	②TR22676
Belt - Alt. - Lower; W/Dual Alts.	1184961	TR22692
Belt - Alt. - Upper; W/Dual Alts.	1186454	TR22676
Belt - Bin Unloader	1187728	C105
Belt - Countershaft - Swivel	1192282	C87
Belt - Countershaft - Thresher Pivot To Center Shaft	1179490	②B122
Belt - Cyl.; W/412-1343 R.P.M.	1161595	2/B99
Belt - Cyl.; W/633-1059 R.P.M.	1161595	2/B99
Belt - Cyl.; W/804-1343 R.P.M.	1147546	2/B93
Belt - Hyd. Pump	1327638	②▲9605HD
Belt - Hydro. Drive	1188636	③B114
Belt - Separator Fan	1176492	B73
Belt - Straw Chopper	1173472	C345
Hose - Lower; W/Hydro. Drive; Ser. No. 19500 & Before		●26524
Hose - Lower; W/Hydro. Drive; Ser. No. 19501 & After		⊖21194
<b>MH3 Hillside</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
<b>1987-1984</b>		
Belt - A.C.	1193749	▲9510HD
Belt - Alt.; W/H.D. Alt.	1195451	②TR22711
Belt - Alt. - Lower; W/Dual Alts.	1184327	▲9625HD
Belt - Countershaft - Swivel	1192282	C87
Belt - Countershaft - Thresher Pivot To Center Shaft	1179490	②B122
Belt - Cyl.; W/804-1343 R.P.M.	1147546	2/B93
Belt - Hyd. Pump	1327638	②▲9605HD
Belt - Hydro. Drive	1188635	②B114
Belt - Separator Fan	1176492	B73
Belt - Straw Chopper	1300867	C190
<b>1983</b>		
Belt - A.C.	1193749	▲9510HD
Belt - Alt.; W/H.D. Alt.	1195451	②TR22711
Belt - Alt. - Lower; W/Dual Alts.	1184327	▲9625HD
Belt - Bin Unloader	1187728	C105
Belt - Countershaft - Swivel	1192282	C87
Belt - Countershaft - Thresher Pivot To Center Shaft	1179490	②B122
Belt - Cyl.; W/804-1343 R.P.M.	1147546	2/B93
Belt - Hyd. Pump	1327638	②▲9605HD
Belt - Hydro. Drive	1188635	②B114
Belt - Separator Fan	1176492	B73
Belt - Straw Chopper	1300867	C190
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
<b>1987-1984</b>		
Belt - A.C.	1193749	▲9510HD
Belt - Alt.; W/H.D. Alt.	1195451	②TR22711
Belt - Alt.; W/Single Alt.	1181482	②TR22676
Belt - Alt. - Lower; W/Dual Alts.	1184961	TR22692
Belt - Alt. - Upper; W/Dual Alts.	1186454	TR22676
Belt - Countershaft - Swivel	1192282	C87
Belt - Countershaft - Thresher Pivot To Center Shaft	1179490	②B122
Belt - Cyl.; W/804-1343 R.P.M.	1147546	2/B93
Belt - Hyd. Pump	1327638	②▲9605HD

Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>MH3 Hillside - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel - Continued</b>		
<b>1987-1984 - Continued</b>		
Belt - Hydro. Drive	1188636	③B114
Belt - Separator Fan	1176492	B73
Belt - Straw Chopper	1300867	C190
<b>1983</b>		
Belt - A.C.	1193749	▲9510HD
Belt - Alt.; W/H.D. Alt.	1195451	②TR22711
Belt - Alt.; W/Single Alt.	1181482	②TR22676
Belt - Alt. - Lower; W/Dual Alts.	1184961	TR22692
Belt - Alt. - Upper; W/Dual Alts.	1186454	TR22676
Belt - Bin Unloader	1187728	C105
Belt - Countershaft - Swivel	1192282	C87
Belt - Countershaft - Thresher Pivot To Center Shaft	1179490	②B122
Belt - Cyl.; W/804-1343 R.P.M.	1147546	2/B93
Belt - Hyd. Pump	1327638	②▲9605HD
Belt - Hydro. Drive	1188636	③B114
Belt - Separator Fan	1176492	B73
Belt - Straw Chopper	1300867	C190
<b>N5</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
<b>1986-1983</b>		
Belt - A.C.	1193420	▲9550HD
Belt - Alt.; W/105A. Alt.	1336137	TR22657
Belt - Clean Grain Elevator	1325847	C116
Belt - Header; W/Std. Speed	1320449	B152
Belt - Impeller	1322418	B83
Belt - Main Drive	1336997	③B210
Belt - Overfeed Auger	1325150	②B126
Belt - Pivot Drive - Left Hand	1310382	B128
Belt - Rad. Fan	1302482	②▲9500HD
Belt - Rear Hood Spreader	1334919	B133
Belt - Separator Fan	1339886	C83
Belt - Shoe Pitman Drive	1336307	②A57
Belt - Straw Chopper J.S.	1344935	C83
Belt - Straw Spreader	1326253	B188
Belt - Tailings Drive	1346200	6865
Belt - Tailings Return	1337000	B94
Hose - Upper - Eng. To Pipe		21194
Hose - Upper - Pipe To Rad.		or ●26521
Hose - Lower - Pipe To Rad.		●26520
		●26525
<b>1982</b>		
Belt - A.C.	1193420	▲9550HD
Belt - Alt.; W/110A. Alt.	1186454	TR22676
Belt - Clean Grain Elevator	1325847	C116
Belt - Header; W/Std. Speed	1320449	B152
Belt - Impeller	1322418	B83
Belt - Main Drive	1336997	③B210
Belt - Overfeed Auger	1325150	②B126
Belt - Pivot Drive - Left Hand	1310382	B128
Belt - Rad. Fan	1302482	②▲9500HD
Belt - Rear Hood Spreader	1334919	B133
Belt - Separator Fan	1339886	C83
Belt - Shoe Pitman Drive	1336307	②A57
Belt - Straw Chopper J.S.	1344935	C83
Belt - Straw Spreader	1326253	B188
Belt - Tailings Drive	1346200	6865
Belt - Tailings Return	1337000	B94
Hose - Upper - Eng. To Pipe		21194
Hose - Upper - Pipe To Rad.		or ●26521
Hose - Lower - Pipe To Rad.		●26520
		●26525
<b>1981</b>		
Belt - A.C.	1193420	▲9550HD
Belt - Alt.; W/H.D. Alt.	1306200	TR22711
Belt - Alt.; W/Std. Alt.	1311297	TR22692
Belt - Clean Grain Elevator	1325847	C116
Belt - Impeller	1322418	B83
Belt - Main Drive	1336997	③B210
Belt - Pivot Drive - Left Hand	1310382	B128
Belt - Rad. Fan	1302482	②▲9500HD
Belt - Rear Hood Spreader	1334919	B133
Belt - Separator Fan	1339886	C83
Belt - Shoe Pitman Drive	1336307	②A57

②Two Required ③Three Required ⊖Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>N5 - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel - Continued</b>		
<b>1981 - Continued</b>		
Belt - Straw Chopper J.S.	1344935	C83
Belt - Straw Spreader	1326253	B188
Belt - Tailings Drive	1346200	6865
Belt - Tailings Return	1337000	B94
Belt - Unloader Drive - Right Hand	1177795	②B74
Hose - Upper - Eng. To Pipe		21194
	or	●26521
Hose - Upper - Pipe To Rad.		●26520
Hose - Lower - Pipe To Rad.		●26525
<b>1980-1979</b>		
Belt - A.C.	1193420	▲9550HD
Belt - Alt.; W/H.D. Alt.	1306200	TR22711
Belt - Alt.; W/Std. Alt.	1311297	TR22692
Belt - Clean Grain Elevator	1325847	C116
Belt - Main Drive	1336997	③B210
Belt - Pivot Drive - Left Hand	1310382	B128
Belt - Rad. Fan	1302482	②▲9500HD
Belt - Rear Hood Spreader	1334919	B133
Belt - Separator Fan	1339886	C83
Belt - Shoe Pitman Drive	1336307	②A57
Belt - Straw Chopper J.S.	1344935	C83
Belt - Straw Spreader	1326253	B188
Belt - Tailings Drive	1346200	6865
Belt - Tailings Return	1337000	B94
Belt - Unloader Drive - Right Hand	1177795	②B74
Hose - Upper - Eng. To Pipe		21194
	or	●26521
Hose - Upper - Pipe To Rad.		●26520
Hose - Lower - Pipe To Rad.		●26525
<b>N6</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
<b>1986-1983</b>		
Belt - A.C.	1193420	▲9550HD
Belt - Alt.; W/105A. Alt.	1336137	TR22657
Belt - Clean Grain Elevator	1325847	C116
Belt - Constant Speed Drive	1320449	B152
Belt - Impeller	1322418	B83
Belt - Main Drive	1336997	③B210
Belt - Overfeed Auger	1325150	②B126
Belt - Pivot Drive - Left Hand	1310382	B128
Belt - Rad. Fan	1302482	②▲9500HD
Belt - Rear Hood Spreader	1334919	B133
Belt - Separator Fan	1339886	C83
Belt - Shoe Pitman Drive	1336307	②A57
Belt - Straw Chopper J.S.	1344935	C83
Belt - Straw Spreader	1326253	B188
Belt - Tailings Drive	1346200	6865
Belt - Tailings Return	1337000	B94
Hose - Upper - Eng. To Pipe		21194
	or	●26521
Hose - Upper - Pipe To Rad.		●26520
Hose - Lower - Pipe To Rad.		●26525
<b>1982</b>		
Belt - A.C.	1193420	▲9550HD
Belt - Alt.; W/110A. Alt.	1186454	TR22676
Belt - Clean Grain Elevator	1325847	C116
Belt - Constant Speed Drive	1320449	B152
Belt - Impeller	1322418	B83
Belt - Main Drive	1336997	③B210
Belt - Overfeed Auger	1325150	②B126
Belt - Pivot Drive - Left Hand	1310382	B128
Belt - Rad. Fan	1302482	②▲9500HD
Belt - Rear Hood Spreader	1334919	B133
Belt - Separator Fan	1339886	C83
Belt - Shoe Pitman Drive	1336307	②A57
Belt - Straw Chopper J.S.	1344935	C83
Belt - Straw Spreader	1326253	B188
Belt - Tailings Drive	1346200	6865
Belt - Tailings Return	1337000	B94
Hose - Upper - Eng. To Pipe		21194
	or	●26521
Hose - Upper - Pipe To Rad.		●26520
Hose - Lower - Pipe To Rad.		●26525

Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>N6 - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel - Continued</b>		
<b>1981</b>		
Belt - A.C.	1193420	▲9550HD
Belt - Alt.; W/H.D. Alt.	1306200	TR22711
Belt - Alt.; W/Std. Alt.	1311297	TR22692
Belt - Clean Grain Elevator	1325847	C116
Belt - Impeller	1322418	B83
Belt - Pivot Drive - Left Hand	1310382	B128
Belt - Rad. Fan	1302482	②▲9500HD
Belt - Rear Hood Spreader	1334919	B133
Belt - Separator Fan	1339886	C83
Belt - Shoe Pitman Drive	1336307	②A57
Belt - Straw Chopper J.S.	1344935	C83
Belt - Straw Spreader	1326253	B188
Belt - Tailings Drive	1346200	6865
Belt - Tailings Return	1337000	B94
Belt - Unloader Drive - Right Hand	1177795	②B74
Hose - Upper - Eng. To Pipe		21194
	or	●26521
Hose - Upper - Pipe To Rad.		●26520
Hose - Lower - Pipe To Rad.		●26525
<b>1980-1979</b>		
Belt - A.C.	1193420	▲9550HD
Belt - Alt.; W/H.D. Alt.	1306200	TR22711
Belt - Alt.; W/Std. Alt.	1311297	TR22692
Belt - Clean Grain Elevator	1325847	C116
Belt - Pivot Drive - Left Hand	1310382	B128
Belt - Rad. Fan	1302482	②▲9500HD
Belt - Rear Hood Spreader	1334919	B133
Belt - Separator Fan	1339886	C83
Belt - Shoe Pitman Drive	1336307	②A57
Belt - Straw Chopper J.S.	1344935	C83
Belt - Straw Spreader	1326253	B188
Belt - Tailings Drive	1346200	6865
Belt - Tailings Return	1337000	B94
Belt - Unloader Drive - Right Hand	1177795	②B74
Hose - Upper - Eng. To Pipe		21194
	or	●26521
Hose - Upper - Pipe To Rad.		●26520
Hose - Lower - Pipe To Rad.		●26525
<b>1978</b>		
Belt - A.C.	1193420	▲9550HD
Belt - Alt.; W/H.D. Alt.	1306200	TR22711
Belt - Alt.; W/Std. Alt.	1311297	TR22692
Belt - Cage Sweep	1301877	A105
Belt - Clean Grain Elevator	1325847	C116
Belt - Pivot Drive - Left Hand	1310382	B128
Belt - Rad. Fan	1302482	②▲9500HD
Belt - Rear Hood Spreader	1334919	B133
Belt - Separator Fan	1339886	C83
Belt - Shoe Pitman Drive	1336307	②A57
Belt - Straw Chopper J.S.	1344935	C83
Belt - Straw Spreader	1326253	B188
Belt - Tailings Drive	1346200	6865
Belt - Tailings Return	1337000	B94
Belt - Unloader Drive - Right Hand	1177795	②B74
Hose - Upper - Eng. To Pipe		21194
	or	●26521
Hose - Upper - Pipe To Rad.		●26520
Hose - Lower - Pipe To Rad.		●26525
<b>N7</b>		
<b>Allis-Chalmers 6-Cyl. 516 Diesel</b>		
<b>1986-1983</b>		
Belt - A.C.	1315910	▲9630HD
Belt - Alt.; W/105A. Alt.	1175687	▲9620HD
Belt - Clean Grain Elevator	1325847	C116
Belt - Constant Speed Drive	1320449	B152
Belt - Impeller	1322418	B83
Belt - Overfeed Auger	1325150	②B126
Belt - Pivot Drive - Left Hand	1310382	B128
Belt - Rad. Fan	4321275	②TR28680
Belt - Rear Hood Spreader	1334919	B133
Belt - Separator Fan	1339886	C83
Belt - Shoe Pitman Drive	1336307	②A57
Belt - Straw Chopper J.S.	1344935	C83
Belt - Straw Spreader	1326253	B188

②Two Required ③Three Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>N7 - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 516 Diesel - Continued</b>		
<b>1986-1983 - Continued</b>		
Belt - Tailings Drive .....	1346200	6865
Belt - Tailings Return .....	1337000	B94
Hose - Upper - Eng. To Pipe .....		②<20397
Hose - By Pass .....		24230
<b>1982</b>		
Belt - A.C. ....	1315910	♣9630HD
Belt - Alt.; W/105A. Alt. ....	1175687	♣9620HD
Belt - Clean Grain Elevator .....	1325847	C116
Belt - Header; W/Std. Speed .....	1320449	B152
Belt - Impeller .....	1322418	B83
Belt - Overfeed Auger .....	1325150	②B126
Belt - Pivot Drive - Left Hand .....	1310382	B128
Belt - Rad. Fan .....	4321275	②TR28680
Belt - Rear Hood Spreader .....	1334919	B133
Belt - Separator Fan .....	1339886	C83
Belt - Shoe Pitman Drive .....	1336307	②A57
Belt - Straw Chopper J.S. ....	1344935	C83
Belt - Straw Spreader .....	1326253	B188
Belt - Tailings Drive .....	1346200	6865
Belt - Tailings Return .....	1337000	B94
Hose - Upper - Eng. To Pipe .....		②<20397
Hose - By Pass .....		24230
<b>1981</b>		
Belt - A.C. ....	1315910	♣9630HD
Belt - Alt.; W/105A. Alt. ....	1175687	②♣9610HD
Belt - Clean Grain Elevator .....	1325847	C116
Belt - Impeller .....	1322418	B83
Belt - Pivot Drive - Left Hand .....	1310382	B128
Belt - Rad. Fan .....	4321275	②TR28680
Belt - Rear Hood Spreader .....	1334919	B133
Belt - Separator Fan .....	1339886	C83
Belt - Shoe Pitman Drive .....	1336307	②A57
Belt - Straw Chopper J.S. ....	1344935	C83
Belt - Straw Spreader .....	1326253	B188
Belt - Tailings Drive .....	1346200	6865
Belt - Tailings Return .....	1337000	B94
Belt - Unloader Drive - Right Hand .....	1177795	②B74
Hose - Upper - Eng. To Pipe .....		②<20397
Hose - By Pass .....		24230
<b>1980-1979</b>		
Belt - A.C. ....	1315910	♣9630HD
Belt - Alt.; W/105A. Alt. ....	1175687	♣9620HD
Belt - Clean Grain Elevator .....	1325847	C116
Belt - Pivot Drive - Left Hand .....	1310382	B128
Belt - Rad. Fan .....	4321275	②TR28680
Belt - Rear Hood Spreader .....	1334919	B133
Belt - Separator Fan .....	1339886	C83
Belt - Shoe Pitman Drive .....	1336307	②A57
Belt - Straw Chopper J.S. ....	1344935	C83
Belt - Straw Spreader .....	1326253	B188
Belt - Tailings Drive .....	1346200	6865
Belt - Tailings Return .....	1337000	B94
Belt - Unloader Drive - Right Hand .....	1177795	②B74
Hose - Upper - Eng. To Pipe .....		②<20397
Hose - By Pass .....		24230
<b>R</b>		
<b>Allis-Chalmers 6-Cyl. 230</b>		
<b>1960-1957</b>		
Belt - Fan & Gen.; Eng. No. 397016 & Before .....	4510744	♣9470HD
Belt - Fan & Gen.; Eng. No. 397017 Thru 408560 .....	4512419	♣9480HD
Belt - Hyd. Pump; Ser. No. 14053 Thru 26500 .....	1117027	TR28483
Belt - Hyd. Pump; Ser. No. 26501 Thru 30000 .....	1128092	TR28463
<b>Ford 6-Cyl. 226</b>		
<b>1953-1951</b>		
Hose - Upper .....		●26611
Hose - Lower; Ser. No. 26000 & Before .....		●26611
Hose - Lower; Ser. No. 26001 & After .....		●26612

Application	OEM No.	Our No.
<b>GLEANER - Continued</b>		
<b>R - Continued</b>		
<b>Hercules 6-Cyl. 237</b>		
<b>1960-1953</b>		
Belt - Fan; Ser. No. 14052 & Before .....	1117027	TR28483
Belt - Hyd. Pump; Ser. No. 13500 & Before ....	1117040	TR28545
Belt - Hyd. Pump; Ser. No. 13501 Thru 14052 .....	1117027	TR28483
Hose - Upper .....		●25528
Hose - Lower .....		●25477
<b>R5; R6</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
<b>1987-1986</b>		
Belt - A.C. ....	1193420	♣9550HD
Belt - Alt.; W/105A. Alt. ....	1336137	TR22657
Belt - Clean Grain Elevator .....	1325847	C116
Belt - Constant Speed Drive .....	1320449	B152
Belt - Impeller .....	1358134	6988
Belt - Main Drive .....	1336997	③B210
Belt - Overfeed Auger .....	1325150	②B126
Belt - Pivot Drive - Left Hand .....	1310382	B128
Belt - Rad. Fan .....	1302482	②♣9500HD
Belt - Separator Fan .....	1339886	C83
Belt - Shoe Pitman Drive .....	1336307	②A57
Belt - Spreader .....	1347561	B133
Belt - Straw Chopper J.S. ....	1344935	C83
Belt - Straw Spreader .....	1326253	B188
Belt - Tailings Drive .....	1346200	6865
Belt - Tailings Return .....	1337000	B94
<b>R7</b>		
<b>Allis-Chalmers 6-Cyl. 516 Diesel</b>		
<b>1987-1986</b>		
Belt - A.C. ....	1315910	♣9630HD
Belt - Alt. ....	1175687	②♣9620HD
Belt - Clean Grain Elevator .....	1325847	C116
Belt - Constant Speed Drive .....	1320449	B152
Belt - Impeller .....	1358134	6988
Belt - Overfeed Auger .....	1325150	②B126
Belt - Pivot Drive - Left Hand .....	1310382	B128
Belt - Rad. Fan .....	4321275	②TR24688
Belt - Rear Hood Spreader .....	1334919	B133
Belt - Separator Fan .....	1339886	C83
Belt - Shoe Pitman Drive .....	1336307	②A57
Belt - Spreader .....	1347561	B133
Belt - Straw Chopper J.S. ....	1344935	C83
Belt - Straw Spreader .....	1326253	B188
Belt - Tailings Drive .....	1346200	6865
Belt - Tailings Return .....	1337000	B94
Hose - Upper - Eng. To Pipe .....		②<20172
Hose - Upper - Pipe To Rad. ....		②<21194
<b>R40</b>		
<b>Deutz 6-Cyl. 374 Diesel</b>		
<b>1991-1988</b>		
Belt - A.C. ....	1352729	♣9560HD
Belt - Alt. ....	1352139	♣9430HD
Belt - Chopper & Impeller .....	1336199	C86
Belt - Constant Speed Drive .....	1320449	B152
Belt - J.S. ....	1333673	C96
<b>R42</b>		
<b>Cummins 6-Cyl. 8.3 L Diesel</b>		
<b>2003-1991</b>		
Belt - A.C. ....	1352729	♣9560HD
Belt - Alt. ....	1352139	♣9430HD
Hose - Upper - Pipe To Rad. ....		24436
Hose - Lower - Pipe To Rad. ....		24432
<b>Deutz 6-Cyl. 374 Diesel</b>		
<b>1996-1992</b>		
Belt - A.C. ....	1352729	♣9560HD
Belt - Alt. ....	1352139	♣9430HD
Hose - Upper - Pipe To Rad. ....		24436
Hose - Lower - Pipe To Rad. ....		24432

②Two Required ③Three Required <Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>R50</b>		
<b>Deutz 6-Cyl. 374 Diesel</b>		
1991-1987		
Belt - A.C. ....	1352729	▲9560HD
Belt - Alt. ....	1352139	▲9430HD
Belt - Chopper & Impeller .....	1336199	C86
Belt - Constant Speed Drive .....	1320449	B152
Belt - J.S. ....	1333673	C96
<b>R52</b>		
<b>Cummins 6-Cyl. 8.3 L Diesel</b>		
2003-1991		
Belt - A.C. ....	1352729	▲9560HD
Belt - Alt. ....	1352139	▲9430HD
Hose - Upper - Pipe To Rad. ....	24436	
Hose - Lower - Pipe To Rad. ....	24432	
<b>R60</b>		
<b>Deutz V-8 817 Diesel</b>		
1991-1990		
Belt - A.C. ....	1193420	▲9550HD
Belt - Alt. ....	1352142	▲9440HD
Belt - Clean Grain Elevator .....	1325847	C116
Belt - Constant Speed Drive .....	1320449	B152
Belt - Fan .....	1339886	C83
Belt - Impeller .....	1359681	②B88
Belt - Pivot Drive - Left Hand .....	1310382	B128
Belt - Separator Drive .....	1325150	②B126
Belt - Shoe Pitman Drive .....	1336307	②A57
Belt - Spreader .....	1347561	B133
Belt - Tailings Drive; W/O Tailings Return Option .....	1345785	A65
Belt - Tailings Drive; W/Tailings Return Option .....	1337000	B94
Belt - Unloader Drive; W/Power Engage .....	1356409	C107
1989-1987		
Belt - A.C. ....	1193420	▲9550HD
Belt - Alt. ....	1352142	▲9440HD
Belt - Clean Grain Elevator .....	1325847	C116
Belt - Constant Speed Drive .....	1320449	B152
Belt - Fan .....	1339886	C83
Belt - Impeller .....	1358134	6988
Belt - Pivot Drive - Left Hand .....	1310382	B128
Belt - Separator Drive .....	1325150	②B126
Belt - Shoe Pitman Drive .....	1336307	②A57
Belt - Spreader .....	1347561	B133
Belt - Tailings Drive; W/O Tailings Return Option .....	1345785	A65
Belt - Tailings Drive; W/Tailings Return Option .....	1345785	A65
Belt - Unloader Drive; W/Power Engage .....	1356409	C107
<b>R62</b>		
<b>Cummins 6-Cyl. 8.3 L Diesel</b>		
2004-1991		
Belt - A.C. ....	1193420	▲9550HD
Belt - Alt - Lower .....	1352142	▲9440HD
Belt - Alt - Upper .....	1352142	▲9440HD
Hose - Upper - Pipe To Rad. ....	24436	
Hose - Lower - Pipe To Rad. ....	24432	
<b>R66</b>		
<b>AGCO 6-Cyl. 8.4 L Diesel</b>		
2009		
Belt - A.C. ....	71148120	▲9510HD
Belt - Clean Grain Elevator .....	71368809	C180
Belt - Rotary Screen .....	71396754	A68
<b>R70</b>		
<b>Deutz V-8 779 Diesel</b>		
1991-1990		
Belt - A.C. ....	1193420	▲9550HD
Belt - Alt. ....	1352142	▲9440HD
Belt - Clean Grain Elevator .....	1325847	C116
Belt - Constant Speed Drive .....	1320449	B152
Belt - Fan .....	1339886	C83

②Two Required ▲Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>GLENER - Continued</b>		
<b>R70 - Continued</b>		
<b>Deutz V-8 779 Diesel - Continued</b>		
1991-1990 - Continued		
Belt - Impeller .....	1359681	②B88
Belt - Pivot Drive - Left Hand .....	1310382	B128
Belt - Separator Drive .....	1325150	②B126
Belt - Shoe Pitman Drive .....	1336307	②A57
Belt - Spreader .....	1347561	B133
Belt - Tailings Drive; W/O Tailings Return Option .....	1345785	A65
Belt - Tailings Drive; W/Tailings Return Option .....	1337000	B94
Belt - Unloader Drive; W/Power Engage .....	1356409	C107
1989-1987		
Belt - A.C. ....	1193420	▲9550HD
Belt - Alt. ....	1352142	▲9440HD
Belt - Clean Grain Elevator .....	1325847	C116
Belt - Constant Speed Drive .....	1320449	B152
Belt - Fan .....	1339886	C83
Belt - Impeller .....	1358134	6988
Belt - Pivot Drive - Left Hand .....	1310382	B128
Belt - Separator Drive .....	1325150	②B126
Belt - Shoe Pitman Drive .....	1336307	②A57
Belt - Spreader .....	1347561	B133
Belt - Tailings Drive; W/O Tailings Return Option .....	1345785	A65
Belt - Tailings Drive; W/Tailings Return Option .....	1345785	A65
Belt - Unloader Drive; W/Power Engage .....	1356409	C107
<b>R72</b>		
<b>Cummins M11 Diesel</b>		
2002-1992		
Belt - A.C. ....	1193420	▲9550HD
Belt - Alt - Lower .....	1352142	▲9440HD
Belt - Alt - Upper .....	1352142	▲9440HD
<b>INTERNATIONAL HARVESTER</b>		
<b>42 McCormick-Deering</b>		
<b>IH C60</b>		
1944-1942		
Belt - Fan .....	18202K	TR22455
<b>52R McCormick-Deering</b>		
<b>IH C60</b>		
1950-1943		
Belt - Fan; W/31 3/4" Belt O.C. ....	368082R1	TR24315
Belt - Fan; W/45 7/8" Belt O.C. ....	18202K	TR22455
Belt - Gen. ....	356059R1	2240
Hose - Upper .....		24232
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24226
<b>64</b>		
<b>IH C60</b>		
1954-1939		
Belt - Fan .....	368082R1	TR24315
Hose - Upper .....		24232
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24226
<b>IH C113</b>		
1954-1952		
Belt - Fan .....		TR24315
Belt - Fan & W.P. ....	273889R1	TR26341
Belt - Gen. ....	49291D	9260
1951-1939		
Belt - Fan .....		TR24315
Belt - Fan & W.P. ....	273889R1	TR28346
Belt - Gen. ....	49291D	9260
<b>IH C123</b>		
1954-1952		
Belt - Fan .....		TR24315
Belt - Fan & W.P. ....	273889R1	TR26341

Agricultural Equipment



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>64 - Continued</b>		
<b>IH C123 - Continued</b>		
<b>1954-1952 - Continued</b>		
Belt - Gen. ....	49291D	9260
<b>1951-1939</b>		
Belt - Fan .....		TR24315
Belt - Fan & W.P. ....	273889R1	TR28346
Belt - Gen. ....	49291D	9260
<b>76</b>		
<b>IH C123</b>		
<b>1959-1956</b>		
Belt - Fan .....		TR24315
Belt - Fan & W.P. ....	273889R1	TR28346
Belt - Gen. ....	49291D	9260
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>93</b>		
<b>IH 4-Cyl. 153</b>		
<b>1968-1962</b>		
Belt - Fan & Gen. ....	151529R1	7440
Hose - Upper .....		②21794
		or ●26507
<b>IH BD154C Diesel</b>		
<b>1968-1962</b>		
Belt - Fan .....	3040315R2	TR22363
Belt - Gen. ....	704449R1	▲9309HD
<b>101</b>		
<b>IH BD220</b>		
<b>1961-1956</b>		
Belt - Fan & Gen. ....	274705R1	TR24438
Hose - Upper .....		②20420
		or ●26507
Hose - Lower .....		●26508
<b>IH D236 Diesel</b>		
<b>1961-1956</b>		
Belt - Fan & Gen. ....	312515R1	▲9525HD
Hose - Upper .....		②20557
Hose - Lower .....		●26507
<b>105</b>		
<b>IH C153</b>		
<b>1970-1967</b>		
Belt - Fan & Gen. ....	596313R1	7445
<b>122 McCormick-Deering; 122C McCormick-Deering</b>		
<b>IH GRD214</b>		
<b>1943</b>		
Belt - Fan .....	28953D	TR28400
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24226
Hose - Lower - Pipe To Rad. ....		24232
<b>123 McCormick-Deering</b>		
<b>IH GRD214</b>		
<b>1942</b>		
Belt - Fan .....	28953D	TR28400
Hose - Upper .....		24230
Hose - Lower .....		②24226
<b>125 McCormick-Deering</b>		
<b>IH GRD214</b>		
<b>1949-1948</b>		
Belt - Fan .....	28953D	TR28400
Hose - Upper .....		24230
Hose - Lower .....		②24226

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>127 McCormick</b>		
<b>IH SD240</b>		
<b>1954-1952</b>		
Belt - Fan & Gen. ....	356437R1	TR28483
Hose - Upper .....		24232
Hose - Lower .....		24232
Hose - By Pass .....		24232
<b>140 McCormick</b>		
<b>IH C164</b>		
<b>1962-1954</b>		
Belt - Fan .....	368085R1	TR24379
Belt - Gen. ....	48878D	▲9313HD
Hose - Upper .....		24228
Hose - Lower .....		24224
<b>IH C169</b>		
<b>1962-1954</b>		
Belt - Fan .....	368085R1	TR24379
Belt - Gen. ....	48878D	▲9313HD
Hose - Upper .....		24228
Hose - Lower .....		24224
<b>IH C175</b>		
<b>1962-1954</b>		
Belt - Fan .....	368085R1	TR24379
Belt - Gen. ....	48878D	▲9313HD
Hose - Upper .....		24228
Hose - Lower .....		24224
<b>141 McCormick</b>		
<b>IH BD240</b>		
<b>1957-1954</b>		
Belt - Fan & Gen. ....	274705R1	TR24438
Hose - Upper .....		24232
Hose - Lower .....		24232
Hose - By Pass .....		24232
<b>IH SD240</b>		
<b>1958-1954</b>		
Belt - Fan & Gen. ....	271670R1	TR24461
Hose - Upper .....		24232
Hose - Lower .....		24232
Hose - By Pass .....		24232
<b>151</b>		
<b>IH BD264</b>		
<b>1961-1958</b>		
Belt - Fan & Gen. ....	274705R1	TR24438
<b>IH D282 Diesel</b>		
<b>1961-1958</b>		
Belt - Fan & Gen.; W/50 3/4" Belt O.C. ....	304436R1	▲9505HD
Belt - Fan & Gen.; W/52 1/4" Belt O.C. ....	312515R1	▲9525HD
<b>160 McCormick-Deering</b>		
<b>IH GRD214</b>		
<b>1953-1951</b>		
Belt - Fan .....	28953D	TR28400
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24226
Hose - Lower - Pipe To Rad. ....		24232
<b>181</b>		
<b>IH BD264</b>		
<b>1966-1963</b>		
Belt - Fan & Gen. ....	274705R1	TR24438
<b>IH D282 Diesel</b>		
<b>1966-1963</b>		
Belt - Fan & Gen.; W/50 3/4" Belt O.C. ....	304436R1	▲9505HD
Belt - Fan & Gen.; W/52 1/4" Belt O.C. ....	312515R1	▲9525HD

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>203</b>		
<b>IH 4-Cyl. 153</b>		
1971-1963		
Belt - Fan & Gen. ....	151529R1	7440
Hose - Upper .....		☞21794
		or ●26507
<b>205</b>		
<b>IH 6-Cyl. 221</b>		
1972-1967		
Belt - W.P. & Gen. ....	403617R1	▲9470HD
<b>303</b>		
<b>IH 6-Cyl. 221</b>		
1968-1965		
Belt - Fan & Gen. ....	170780R1	▲9470HD
<b>IH BD220</b>		
1968-1965		
Belt - Fan & Gen. ....	274705R1	TR24438
Hose - Upper .....		☞20611
Hose - Lower .....		●26509
<b>315</b>		
<b>IH 6-Cyl. 221</b>		
1970-1967		
Belt - W.P. & Gen. ....	403617R1	▲9470HD
Hose - Upper .....		●26522
<b>402</b>		
<b>IH D282 Diesel</b>		
1971-1966		
Belt - W.P. & Alt. ....	379966R1	▲9540HD
Hose - By Pass .....		28441
<b>403</b>		
<b>IH 6-Cyl. 282</b>		
1973-1962		
Belt - Gen. ....	170780R1	▲9470HD
Belt - W.P. & Alt.; W/53 1/4" Belt O.C. ....	394013R1	▲9530HD
Belt - W.P. & Alt.; W/54 1/4" Belt O.C. ....	379966R1	▲9540HD
Hose - Upper .....		●26510
Hose - Lower .....		●26509
<b>IH 6-Cyl. 282 Diesel</b>		
1973-1962		
Belt - Fan .....	388024R1	TR24355
Belt - Gen. ....		▲9530HD
Belt - W.P. & Gen. ....	379966R1	▲9540HD
Hose - Upper .....		●26510
<b>453 Hillside</b>		
<b>IH 6-Cyl. 301</b>		
1977-1974		
Belt - Fan .....	533739R1	TR22495
Belt - W.P. & Alt. ....	403617R1	▲9470HD
Hose - By Pass .....		20338
<b>IH 6-Cyl. 301 Diesel</b>		
1977-1974		
Hose - By Pass .....		20338
<b>IH 6-Cyl. 360 Diesel</b>		
1977-1974		
Belt - W.P. & Alt. ....	532746R1	TR22648
<b>503</b>		
<b>IH 6-Cyl. 282</b>		
1969-1962		
Belt - Gen. ....	170780R1	▲9470HD
Hose - Upper .....		●26510
Hose - Lower .....		●26509

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>503 - Continued</b>		
<b>IH D301 Diesel</b>		
1969-1962		
Belt - Gen. ....	379966R1	▲9540HD
Belt - W.P. & Gen. ....	379966R1	▲9540HD
Hose - Upper .....		●26510
<b>615</b>		
<b>IH 6-Cyl. 263</b>		
1975-1971		
Belt - A.C. ....	936331R1	▲9580HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C. ....	403617R1	▲9470HD
Belt - W.P. & Alt.; W/47 3/4" Belt O.C. ....		▲9476HD
Hose - Upper; Early .....		●26516
Hose - Upper; Late .....		●26512
Hose - Lower .....		●26513
Hose - By Pass .....		20338
<b>715</b>		
<b>IH 6-Cyl. 301</b>		
1979-1973		
Belt - A.C. ....	936331R1	▲9580HD
Belt - Alt. & W.P. ....	533824R91	②7541
Belt - Fan; W/50 1/4" Belt O.C. ....	533739R1	TR22495
Belt - Fan; W/54 5/8" Belt O.C. ....	533824R91	②7541
Belt - Shaker Shaft Drive; W/Std. Drive .....	564494R2	C110
Belt - Tailings Delivery Auger .....	627297R1	6942
Belt - Unloader Drive; W/Std. Drive .....	559064R1	C144
Belt - Unloader J.S. & Knife Drive .....	178019C1	C99
1972		
Belt - A.C. ....	936331R1	▲9580HD
Belt - Alt. & W.P. ....	533824R91	②7541
Belt - Fan; W/50 1/4" Belt O.C. ....	533739R1	TR22495
Belt - Fan; W/54 5/8" Belt O.C. ....	533824R91	7541
Belt - Shaker Shaft Drive; W/Std. Drive .....	564494R2	C110
Belt - Tailings Delivery Auger .....	627297R1	6942
Belt - Unloader Drive; W/Std. Drive .....	559064R1	C144
Belt - Unloader J.S. & Knife Drive .....	178019C1	C99
1971		
Belt - A.C. ....	936331R1	▲9580HD
Belt - Alt. & W.P. ....	403617R1	▲9470HD
Belt - Fan; W/50 1/4" Belt O.C. ....	533739R1	TR22495
Belt - Fan; W/54 5/8" Belt O.C. ....	533824R91	7541
Belt - Shaker Shaft Drive; W/Std. Drive .....	564494R2	C110
Belt - Tailings Delivery Auger .....	627297R1	6942
Belt - Unloader Drive; W/Std. Drive .....	559064R1	C144
Belt - Unloader J.S. & Knife Drive .....	178019C1	C99
<b>IH 6-Cyl. 301 Diesel</b>		
1979		
Belt - A.C. ....	936331R1	▲9580HD
Belt - Alt. & W.P. ....	394013R1	▲9530HD
Belt - Fan; W/50 1/4" Belt O.C. ....	533739R1	TR22495
Belt - Fan; W/54 5/8" Belt O.C. ....	533824R91	②7541
Belt - Fan, W.P. & Alt. ....	395539R1	▲9630HD
Belt - Shaker Shaft Drive; W/Std. Drive .....	564494R2	C110
Belt - Tailings Delivery Auger .....	627297R1	6942
Belt - Unloader Drive; W/Std. Drive .....	559064R1	C144
Belt - Unloader J.S. & Knife Drive .....	178019C1	C99
Hose - By Pass .....		28442
<b>815</b>		
<b>IH 6-Cyl. 345 Diesel</b>		
1978-1975		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan .....	164999C92	②TR30537
Belt - Fan, Alt. & W.P. ....	402253R91	②▲9680HD
Belt - Gov. ....	532031R2	7525
Belt - Knife Drive .....	178019C1	C99
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Straw Spreader .....	196370C1	B210
Belt - Unloader J.S. ....	160173C1	C93

②Two Required ☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>815 - Continued</b>		
<b>IH 6-Cyl. 407 Diesel</b>		
<b>1981-1974</b>		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan ..... ②	164999C92	TR30537
Belt - Fan, Alt. & W.P. ....	402253R91	▲9680HD
Belt - Gov. ....	532031R2	7525
Belt - Knife Drive .....	178019C1	C99
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Straw Spreader .....	196370C1	B210
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
Hose - By Pass .....		≈<20573
<b>1973-1972</b>		
Belt - Fan ..... ②	164999C92	TR30537
Belt - Fan, W.P. & Gen. ....	528419R91	TR22664
Belt - Platform J.S. Drive .....	150816C1	D162
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Straw Spreader .....	161821C1	B210
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
Hose - By Pass .....		≈<20573
<b>1971-1968</b>		
Belt - Fan ..... ②	164999C92	TR30537
Belt - Fan, W.P. & Gen. ....	528419R91	TR22664
Belt - Platform J.S. Drive .....	150816C1	D162
Belt - Rotary Air Screen Drive; W/85" Belt O.C. ....	168725C1	A83
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
Hose - By Pass .....		≈<20573
<b>IH 6-Cyl. 414 Diesel</b>		
<b>1981-1974</b>		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan ..... ②	164999C92	TR30537
Belt - Fan, Alt. & W.P. ....	402253R91	▲9680HD
Belt - Gov. ....	532031R2	7525
Belt - Knife Drive .....	178019C1	C99
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Straw Spreader .....	196370C1	B210
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
<b>1973-1972</b>		
Belt - Fan ..... ②	164999C92	TR30537
Belt - Platform J.S. Drive .....	150816C1	D162
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Straw Spreader .....	161821C1	B210
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
<b>1971-1968</b>		
Belt - Fan ..... ②	164999C92	TR30537
Belt - Platform J.S. Drive .....	150816C1	D162
Belt - Rotary Air Screen Drive; W/85" Belt O.C. ....	168725C1	A83
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
<b>IH V-8 345</b>		
<b>1981-1974</b>		
Belt - A.C. ....	167031C1	▲9510HD
Belt - Fan ..... ②	164999C92	TR30537
Belt - Fan, Alt. & W.P. ....	402253R91	▲9680HD
Belt - Gov. ....	532031R2	7525
Belt - Knife Drive .....	178019C1	C99
Belt - Rotary Air Screen Drive .....	700709489	A76
Belt - Separator Drive .....	166598C2	B199
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Straw Spreader .....	196370C1	B210

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>815 - Continued</b>		
<b>IH V-8 345 - Continued</b>		
<b>1981-1974 - Continued</b>		
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26517
Hose - Lower .....		●26524
<b>1973-1972</b>		
Belt - Fan ..... ②	164999C92	TR30537
Belt - Platform J.S. Drive .....	150816C1	D162
Belt - Rotary Air Screen Drive .....	700709489	A76
Belt - Separator Drive .....	166598C2	B199
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Straw Spreader .....	161821C1	B210
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26517
Hose - Lower .....		●26524
<b>1971-1968</b>		
Belt - Fan ..... ②	164999C92	TR30537
Belt - Platform J.S. Drive .....	150816C1	D162
Belt - Rotary Air Screen Drive .....	38331K	A75
Belt - Separator Drive .....	166598C2	B199
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26517
Hose - Lower .....		●26524
<b>915</b>		
<b>IH 6-Cyl. 345 Diesel</b>		
<b>1978-1974</b>		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan ..... ②	164999C92	TR30537
Belt - Fan, Alt. & W.P.; W/A.C. ....	402253R91	▲9680HD
Belt - Gov. ....	532031R2	7525
Belt - Knife Drive .....	178019C1	C99
Belt - Rotary Air Screen Drive .....	700709489	A76
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Unloader J.S. ....	160173C1	C93
<b>IH 6-Cyl. 407 Diesel</b>		
<b>1981-1974</b>		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan ..... ②	164999C92	TR30537
Belt - Fan, Alt. & W.P.; W/A.C. ....	402253R91	▲9680HD
Belt - Gov. ....	532031R2	7525
Belt - Knife Drive .....	178019C1	C99
Belt - Rotary Air Screen Drive .....	700709489	A76
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
Hose - By Pass .....		≈<20573
<b>1973-1972</b>		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan ..... ②	164999C92	TR30537
Belt - Fan, Alt. & W.P.; W/A.C. ....	402253R91	▲9680HD
Belt - Fan, W.P. & Gen. ....	528419R91	TR22664
Belt - Rotary Air Screen Drive .....	700709489	A76
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
Hose - By Pass .....		≈<20573
<b>1971-1969</b>		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan ..... ②	164999C92	TR30537
Belt - Fan, Alt. & W.P.; W/A.C. ....	402253R91	▲9680HD
Belt - Fan, W.P. & Gen. ....	528419R91	TR22664
Belt - Rotary Air Screen Drive; W/77" Belt O.C. ....	38331K	A75
Belt - Rotary Air Screen Drive; W/85" Belt O.C. ....	168725C1	A83
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Straw Spreader .....	161821C1	B210

②Two Required ≈<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>915 - Continued</b>		
<b>IH 6-Cyl. 407 Diesel - Continued</b>		
<b>1971-1969 - Continued</b>		
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
Hose - By Pass .....		≧20573
<b>IH 6-Cyl. 414 Diesel</b>		
<b>1981-1974</b>		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan .....	164999C92	②TR30537
Belt - Fan, Alt. & W.P.; W/A.C. ....	402253R91	②▲9680HD
Belt - Gov. ....	532031R2	7525
Belt - Knife Drive .....	178019C1	C99
Belt - Rotary Air Screen Drive .....	700709489	A76
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
<b>1973-1972</b>		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan .....	164999C92	②TR30537
Belt - Fan, Alt. & W.P.; W/A.C. ....	402253R91	②▲9680HD
Belt - Rotary Air Screen Drive .....	700709489	A76
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
<b>1971-1969</b>		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan .....	164999C92	②TR30537
Belt - Fan, Alt. & W.P.; W/A.C. ....	402253R91	②▲9680HD
Belt - Rotary Air Screen Drive; W/77" Belt O.C. ....	38331K	A75
Belt - Rotary Air Screen Drive; W/85" Belt O.C. ....	168725C1	A83
Belt - Shaker Shaft Drive; W/265 R.P.M. ....	564494R2	C110
Belt - Shaker Shaft Drive; W/280 R.P.M. ....	632702R1	C108
Belt - Straw Spreader .....	161821C1	B210
Belt - Unloader J.S. ....	160173C1	C93
Hose - Upper .....		●26511
<b>1420</b>		
<b>IH 6-Cyl. 358 Diesel</b>		
<b>1986-1981</b>		
Belt - A.C. ....	280210C2	▲9540HD
Belt - Aux. Pump .....	191288C2	C92
Belt - Fan, Alt. & W.P. ....	130724C91	②▲9700HD
Belt - Feeder .....	186377C1	C128
Belt - Feeder J.S. ....	197412C1	C128
Belt - Tailings Elevator .....	674965R1	C101
Hose - Upper .....		≧20046
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		≧20206
<b>1440; 1460</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
<b>1986-1977</b>		
Belt - A.C. ....	874097C1	▲9395HD
Belt - Aux. Pump .....	191288C2	C92
Belt - Cleaner Fan J.S. ....	191305C1	C108
Belt - Fan, Alt. & W.P. ....	537072R91	②TR22648
Belt - Hyd. Reel Drive; W/47" Feeder; W/O Rock Trap .....	197411C1	C128
Belt - Hyd. Reel Drive; W/54 1/2" Feeder; W/O Rock Trap .....	197414C2	C144
Belt - J.S.; W/Slow Speed Fan .....	610521R1	B71
Belt - Unloader J.S. ....	191290C1	C130
<b>1480</b>		
<b>IH DT466 Diesel</b>		
<b>1986-1978</b>		
Belt - A.C. ....	874097C1	▲9395HD
Belt - Aux. Pump .....	191288C2	C92
Belt - Fan J.S.; W/Std. Speed .....	188213C1	C124
Belt - Hyd. Reel Drive; W/54 1/2" Feeder; W/O Rock Trap .....	197414C2	C144

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>1480 - Continued</b>		
<b>IH DT466 Diesel - Continued</b>		
<b>1986-1978 - Continued</b>		
Belt - J.S.; W/Slow Speed Fan .....	610521R1	B71
<b>JOHN DEERE</b>		
<b>12A</b>		
<b>John Deere LUC</b>		
<b>1955-1954</b>		
Belt - Fan .....	L4264T	TR24308
<b>John Deere LUH</b>		
<b>1955-1954</b>		
Belt - Fan .....	L4264T	TR24308
<b>25 Pull</b>		
<b>John Deere HA92</b>		
<b>1955-1954</b>		
Belt - Fan .....	T199T	7400
Belt - Fan & Gen. ....	T200T	7340
<b>30 Pull</b>		
<b>John Deere HA92</b>		
<b>1960-1956</b>		
Belt - Fan .....	T199T	7400
Belt - Fan & Gen. ....	T200T	7340
<b>40SP</b>		
<b>John Deere HA115G</b>		
<b>1965-1960</b>		
Belt - Fan; Ser. No. 11919 & Before .....	T199T	7400
Belt - Fan; Ser. No. 11920 & After .....	T12042T	7410
<b>45SP</b>		
<b>Hercules JX4C3</b>		
<b>1969-1954</b>		
Belt - Fan & Gen. ....	P46676	▲9500HD
<b>John Deere HA145</b>		
<b>1969-1954</b>		
Belt - Fan; Ser. No. 21501 Thru 46000 .....	H24450H	7280
Belt - Fan & Alt.; Ser. No. 46001 & After .....	AT23500	②7405
Belt - Fan & Gen.; Ser. No. 8432 Thru 21500 .....		7450
Belt - Gen.; Ser. No. 21501 Thru 46000 .....	T12042	7410
Hose - Upper .....		≧20065
		or ●25526
Hose - Lower .....		≧20065
		or ●25526
<b>John Deere HA155</b>		
<b>1969-1954</b>		
Belt - Fan; Ser. No. 21501 Thru 46000 .....	H24450H	7280
Belt - Fan & Alt.; Ser. No. 46001 & After .....	AT23500	②7405
Belt - Fan & Gen.; Ser. No. 8432 Thru 21500 .....		7450
Belt - Gen.; Ser. No. 21501 Thru 46000 .....	T12042	7410
<b>John Deere HB145</b>		
<b>1969-1954</b>		
Belt - Fan; Ser. No. 21501 Thru 46000 .....	H24450H	7280
Belt - Fan & Alt.; Ser. No. 46001 & After .....	AT23500	②7405
Belt - Fan & Gen.; Ser. No. 8432 Thru 21500 .....		7450
Belt - Gen.; Ser. No. 21501 Thru 46000 .....	T12042	7410
<b>55</b>		
<b>Hercules QXD3</b>		
<b>1969-1954</b>		
Belt - Fan & Alt. ....	AT23500	②7405
Belt - Fan & Gen.; Ser. No. 55-12050 & Before .....	P40280H	TR28514
Belt - Fan & Gen.; Ser. No. 55-12051 Thru 55-46800 .....	P43532H	TR28565
Belt - Fan & Gen.; Ser. No. 55-46801 Thru 55-57000 .....	T626T	7480
Belt - Fan & Gen.; Ser. No. 55-57001 & After ..	H24268	7330

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>55 - Continued</b>		
<b>Hercules QXD3 - Continued</b>		
<b>1969-1954 - Continued</b>		
Hose - Upper - Eng. To Pipe .....		24232
Hose - Upper - Pipe To Rad. ....		24232
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>Hercules QXD3 Diesel</b>		
<b>1969-1954</b>		
Belt - Fan & Alt. ....	AT23500	②7405
Belt - Fan & Gen.; Ser. No. 55-12050 & Before .....	P40280H	TR28514
Belt - Fan & Gen.; Ser. No. 55-12051 Thru 55-46800 .....	P43532H	TR28565
Belt - Fan & Gen.; Ser. No. 55-46801 Thru 55-57000 .....	T626T	7480
Belt - Fan & Gen.; Ser. No. 55-57001 & After ..	H30634H	▲9380HD
Hose - Upper - Eng. To Pipe .....		24232
Hose - Upper - Pipe To Rad. ....		24232
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>95</b>		
<b>John Deere 6-Cyl. 303</b>		
<b>1969-1958</b>		
Belt - Fan & Alt. ....	AT23500	②7405
<b>John Deere 6-Cyl. 303 Diesel</b>		
<b>1969-1958</b>		
Belt - Fan & Alt. ....	AT23500	②7405
<b>John Deere 248D Diesel</b>		
<b>1969-1958</b>		
Belt - Fan; Ser. No. 95-20001 Thru 95-35000 .....	H30634H	▲9380HD
Belt - Fan; Ser. No. 95-9001 Thru 95-20000 ..	H23725H	TR24400
Belt - Fan & Alt. ....		7410
Belt - Fan & Gen.; Ser. No. 95-9000 & Before .....	T626T	7480
Belt - Hyd. Pump; Ser. No. 95-35001 & After ..	H63772	▲9540HD
Belt - P.S.; Ser. No. 95-9000 & Before .....	P50471H	7450
Belt - P.S.; Ser. No. 95-9001 Thru 95-15000 ..	H23725H	TR24400
Belt - W.P.; Ser. No. 95-9001 & After .....	P50471H	7450
Belt - W.P. & Gen.; Ser. No. 95-9001 Thru 95-35000 .....	T12031T	7470
<b>John Deere 248G</b>		
<b>1969-1958</b>		
Belt - Fan; Ser. No. 95-20001 Thru 95-35000 .....	H30634H	▲9380HD
Belt - Fan; Ser. No. 95-9001 Thru 95-20000 ..	H23725H	TR24400
Belt - Fan & Alt. ....		7410
Belt - Fan & Gen.; Ser. No. 95-9000 & Before .....	T626T	7480
Belt - Hyd. Pump; Ser. No. 95-35001 & After ..	H63772	▲9540HD
Belt - P.S.; Ser. No. 95-9000 & Before .....	P50471H	7450
Belt - P.S.; Ser. No. 95-9001 Thru 95-15000 ..	H23725H	TR24400
Belt - W.P. & Gen.; Ser. No. 95-9001 Thru 95-35000 .....	T12031T	7470
<b>John Deere HG217G</b>		
<b>1969-1958</b>		
Belt - Fan .....		TR22380
Belt - Gov. ....		②▲9370HD
Belt - W.P. & Gen. ....		7470
Hose - Upper .....		②24224
Hose - Lower; Ser. No. 60000 & Before .....		③<20065
Hose - Lower; Ser. No. 60001 & After .....		③<20433
		or ●25526
<b>105SP</b>		
<b>John Deere HA341D Diesel</b>		
<b>1969-1961</b>		
Belt - Fan; Ser. No. 105-3001 Thru 105-4500 .....	H30634H	▲9380HD
Belt - Fan; Ser. No. 105-4501 & After .....	AR32661R	②7560
Belt - P.S. ....		TR22397

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>105SP - Continued</b>		
<b>John Deere HA341G</b>		
<b>1969-1961</b>		
Belt - Fan & Gen.; Ser. No. 105-4500 & Before .....	T644T	7460
Belt - Fan & Gen.; Ser. No. 105-4501 & After ..	AR32659R	②7555
Belt - P.S. ....		TR22397
<b>3300SP</b>		
<b>John Deere 6-Cyl. 219</b>		
<b>1976-1975</b>		
Belt - A.C. ....	H86273	▲9510HD
Belt - Alt. & W.P. ....	H80897	▲9500HD
Belt - Clean Grain Elevator .....	H87648	C106
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86273	▲9510HD
Belt - Rotary Deflector .....	H86039	6870
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
Hose - Upper .....		●25526
Hose - Lower .....		③<20351
Hose - By Pass .....		28442
<b>1974</b>		
Belt - A.C.; Ser. No. 100001 Thru 101300 .....	H63772	▲9540HD
Belt - Alt. & W.P. ....	H80897	▲9500HD
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86273	▲9510HD
Belt - Rotary Deflector .....	H86039	6870
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
Hose - Upper .....		●25526
Hose - Lower .....		③<20351
Hose - By Pass .....		28442
<b>1973-1970</b>		
Belt - A.C. ....	H80896	▲9560HD
Belt - Alt. & W.P. ....	H80897	▲9500HD
Belt - Eng. Fan .....	H79236	▲9635HD
Belt - Eng. Fan Countershaft .....	H79235	②▲9590HD
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
Hose - Upper .....		●25526
Hose - Lower .....		③<20351
Hose - By Pass .....		28442
<b>John Deere 6-Cyl. 219 Diesel</b>		
<b>1976-1975</b>		
Belt - A.C. ....	H86273	▲9510HD
Belt - Alt. & W.P. ....	H80897	▲9500HD
Belt - Clean Grain Elevator .....	H87648	C106
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86273	▲9510HD
Belt - Rotary Deflector .....	H86039	6870
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
<b>1974</b>		
Belt - A.C.; Ser. No. 100001 Thru 101300 .....	H63772	▲9540HD
Belt - Alt. & W.P. ....	H80897	▲9500HD
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86273	▲9510HD
Belt - Rotary Deflector .....	H86039	6870
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
<b>1973-1971</b>		
Belt - A.C. ....	H81742	▲9530HD
Belt - Alt. & W.P. ....	H80897	▲9500HD
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan .....	H79236	▲9635HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86273	▲9510HD
Belt - Eng. Fan Countershaft .....	H79235	②▲9590HD
Belt - Shoe Grain Supply Auger .....	H79285	B136

②Two Required ③Three Required ③-Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>3300SP - Continued</b>		
<b>John Deere 6-Cyl. 219 Diesel - Continued</b>		
<b>1973-1971 - Continued</b>		
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
<b>1970</b>		
Belt - A.C. ....	H81742	▲9530HD
Belt - Alt. & W.P. ....	H80897	▲9500HD
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan; W/A.C. ....	H86271	▲9650HD
Belt - Eng. Fan; W/O A.C. ....	H79236	▲9635HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86273	▲9510HD
Belt - Eng. Fan Countershaft .....	H79235	②▲9590HD
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
<b>4400SP</b>		
<b>Chevrolet 6-Cyl. 292</b>		
<b>1979-1977</b>		
Belt - Alt. & W.P. ....	H30634	▲9380HD
Belt - Clean Grain Elevator .....	H87648	C106
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan; W/A.C. ....	H94373	▲9660HD
Belt - Eng. Fan; W/O A.C. ....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	▲9485HD
Belt - Platform & Corn Head - Lower .....	AH87197	③6965
Belt - Rotary Deflector .....	H86039	6870
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
Hose - Upper .....		●25526
Hose - Lower .....		●26513
Hose - By Pass .....		20563
<b>1976-1975</b>		
Belt - Alt. & W.P. ....	H30634	▲9380HD
Belt - Clean Grain Elevator .....	H87648	C106
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	▲9485HD
Belt - Platform & Corn Head - Lower .....	AH87197	③6965
Belt - Rotary Deflector .....	H86039	6870
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
Hose - Upper .....		●25526
Hose - Lower .....		●26513
Hose - By Pass .....		20563
<b>1974</b>		
Belt - Alt. & W.P. ....	H30634	▲9380HD
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	▲9485HD
Belt - Platform & Corn Head - Lower .....	AH87197	③6965
Belt - Rotary Deflector .....	H86039	6870
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
Hose - Upper .....		●25526
Hose - Lower .....		●26513
Hose - By Pass .....		20563
<b>1973-1970</b>		
Belt - A.C. ....	H80896	▲9560HD
Belt - Alt. & W.P. ....	H30634	▲9380HD
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan .....	H79236	▲9635HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	▲9485HD
Belt - Eng. Fan Countershaft .....	H79235	▲9590HD
Belt - Platform & Corn Head - Lower .....	AH87197	③6965
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
Hose - Upper .....		●25526
Hose - Lower .....		●26513
Hose - By Pass .....		20563

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>4400SP - Continued</b>		
<b>John Deere 6-Cyl. 239 Diesel</b>		
<b>1979-1977</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P. ....	H82724	▲9570HD
Belt - Clean Grain Elevator .....	H87648	C106
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan; W/A.C. ....	H94373	▲9660HD
Belt - Eng. Fan; W/O A.C. ....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	▲9485HD
Belt - Platform & Corn Head - Lower .....	AH87197	③6965
Belt - Rotary Deflector .....	H86039	6870
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
<b>1976</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P.; Ser. No. 202603 & Before ..	H80896	▲9560HD
Belt - Alt. & W.P.; Ser. No. 202604 & After ....	H82724	▲9570HD
Belt - Clean Grain Elevator .....	H87648	C106
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	▲9485HD
Belt - Platform & Corn Head - Lower .....	AH87197	③6965
Belt - Rotary Deflector .....	H86039	6870
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
<b>1975</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P. ....	H80896	▲9560HD
Belt - Clean Grain Elevator .....	H87648	C106
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	▲9485HD
Belt - Platform & Corn Head - Lower .....	AH87197	③6965
Belt - Rotary Deflector .....	H86039	6870
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
<b>1974</b>		
Belt - Alt. & W.P. ....	H80896	▲9560HD
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	▲9485HD
Belt - Platform & Corn Head - Lower .....	AH87197	③6965
Belt - Rotary Deflector .....	H86039	6870
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
<b>1973-1972</b>		
Belt - A.C. ....	H80896	▲9560HD
Belt - Alt. & W.P. ....	H80897	▲9500HD
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan .....	H79236	▲9635HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	▲9485HD
Belt - Eng. Fan Countershaft .....	H79235	▲9590HD
Belt - Platform & Corn Head - Lower .....	AH87197	③6965
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
<b>1971-1970</b>		
Belt - A.C. ....	H80896	▲9560HD
Belt - Cyl. ....	AH80500	③B89
Belt - Eng. Fan .....	H79236	▲9635HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	▲9485HD
Belt - Eng. Fan Countershaft .....	H79235	▲9590HD
Belt - Platform & Corn Head - Lower .....	AH87197	③6965
Belt - Shoe Grain Supply Auger .....	H79285	B136
Belt - Straw Chopper - Front .....	H20407	C115
Belt - Straw Spreader .....	H80159	B110
<b>4420</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
<b>1986-1985</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P. ....	H101813	▲9580HD

②Two Required ③Three Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>4420 - Continued</b>		
<b>John Deere 6-Cyl. 359 Diesel - Continued</b>		
<b>1986-1985 - Continued</b>		
Belt - Beater Drive; W/100 Percent Beater Speed .....	H86039	<b>6870</b>
Belt - Beater Drive; W/150 Percent Beater Speed .....	H101352	<b>AP64</b>
Belt - Cyl. ....	AH80500	<b>③B89</b>
Belt - Eng. Fan; W/A.C. ....	H94373	<b>♣9660HD</b>
Belt - Eng. Fan; W/O A.C. ....	H86271	<b>♣9650HD</b>
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	<b>♣9485HD</b>
Belt - Platform & Corn Head - Lower .....	AH87197	<b>③6965</b>
Belt - Shoe Grain Supply Auger .....	H79285	<b>B136</b>
Belt - Straw Chopper - Front .....	H20407	<b>C115</b>
Belt - Straw Spreader .....	H80159	<b>B110</b>
<b>1984</b>		
Belt - A.C. ....	H86275	<b>♣9485HD</b>
Belt - Alt. & W.P. ....	H101813	<b>♣9580HD</b>
Belt - Beater Drive; W/100 Percent Beater Speed .....	H86039	<b>6870</b>
Belt - Beater Drive; W/150 Percent Beater Speed .....	H101352	<b>AP64</b>
Belt - Cyl. ....	AH80500	<b>③B89</b>
Belt - Eng. Fan; W/A.C. ....	H94373	<b>♣9660HD</b>
Belt - Eng. Fan; W/O A.C. ....	H86271	<b>♣9650HD</b>
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	<b>♣9485HD</b>
Belt - Platform & Corn Head - Lower .....	AH87197	<b>6965</b>
Belt - Shoe Grain Supply Auger .....	H79285	<b>B136</b>
Belt - Straw Chopper - Front .....	H20407	<b>C115</b>
Belt - Straw Spreader .....	H80159	<b>B110</b>
<b>1983-1982</b>		
Belt - A.C. ....	H86275	<b>♣9485HD</b>
Belt - Alt. & W.P. ....	H101813	<b>♣9580HD</b>
Belt - Beater Drive; W/100 Percent Beater Speed .....	H86039	<b>6870</b>
Belt - Beater Drive; W/150 Percent Beater Speed .....	H101352	<b>AP64</b>
Belt - Cyl. ....	AH80500	<b>③B89</b>
Belt - Eng. Fan; W/A.C. ....	H94373	<b>♣9660HD</b>
Belt - Eng. Fan; W/O A.C. ....	H86271	<b>♣9650HD</b>
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	<b>♣9485HD</b>
Belt - Platform & Corn Head - Lower .....	AH87197	<b>③6965</b>
Belt - Shoe Grain Supply Auger .....	H79285	<b>B136</b>
Belt - Straw Chopper - Front .....	H20407	<b>C115</b>
Belt - Straw Spreader .....	H80159	<b>B110</b>
<b>1981-1980</b>		
Belt - A.C. ....	H86275	<b>♣9485HD</b>
Belt - Alt. & W.P. ....	H82724	<b>②♣9570HD</b>
Belt - Beater Drive; W/100 Percent Beater Speed .....	H86039	<b>6870</b>
Belt - Beater Drive; W/150 Percent Beater Speed .....	H101352	<b>AP64</b>
Belt - Cyl. ....	AH80500	<b>③B89</b>
Belt - Eng. Fan; W/A.C. ....	H94373	<b>♣9660HD</b>
Belt - Eng. Fan; W/O A.C. ....	H86271	<b>♣9650HD</b>
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86275	<b>♣9485HD</b>
Belt - Platform & Corn Head - Lower .....	AH87197	<b>③6965</b>
Belt - Shoe Grain Supply Auger .....	H79285	<b>B136</b>
Belt - Straw Chopper - Front .....	H20407	<b>C115</b>
Belt - Straw Spreader .....	H80159	<b>B110</b>
<b>4435</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
<b>1989</b>		
Belt - W.P. ....	AR72036	<b>②♣9590HD</b>
<b>6600</b>		
<b>John Deere 6-Cyl. 329</b>		
<b>1978</b>		
Belt - Charge Pump; W/Hydro. Drive .....	T199T	<b>7400</b>
Belt - Clean Grain Elevator .....	H77766	<b>C152</b>
Belt - Clean Grain Elevator Countershaft .....	H27433	<b>C90</b>
Belt - Cyl.; W/280-845 R.P.M. ....	AH80500	<b>③69100</b>
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	<b>③B102</b>
Belt - Eng. Fan .....	H86272	<b>♣9670HD</b>
Belt - Eng. Fan Countershaft .....	H79235	<b>♣9590HD</b>

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6600 - Continued</b>		
<b>John Deere 6-Cyl. 329 - Continued</b>		
<b>1978 - Continued</b>		
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	<b>C152</b>
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	<b>③C83</b>
Belt - Propulsion - Upper; Exc. Sidehill .....	AH21301	<b>②D100</b>
Belt - Propulsion - Upper; Ser. No. 305672 & Before; Sidehill .....	AH21301	<b>②D100</b>
Belt - Rotary Deflector .....	H86039	<b>6870</b>
Belt - Straw Chopper - Rear .....	H79789	<b>C225</b>
Belt - Straw Spreader .....	H26858	<b>B142</b>
Belt - Tailings - Lower Auger .....	N110085	<b>C128</b>
Belt - U-Joint Loading Auger .....	H23950	<b>CX120</b>
Belt - Unloader Auger Countershaft; Exc. Sidehill .....	H76150	<b>C60</b>
Belt - Unloader Auger Countershaft; Ser. No. 305672 & Before; Sidehill .....	H76150	<b>C60</b>
Hose - Upper .....		<b>●26511</b>
Hose - By Pass .....		<b>24224</b>
<b>1977-1975</b>		
Belt - Charge Pump; W/Hydro. Drive .....	T199T	<b>7400</b>
Belt - Clean Grain Elevator .....	H77766	<b>C152</b>
Belt - Clean Grain Elevator Countershaft .....	H27433	<b>C90</b>
Belt - Cyl.; W/280-845 R.P.M. ....	AH80500	<b>③69100</b>
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	<b>③B102</b>
Belt - Eng. Fan .....	H86272	<b>♣9670HD</b>
Belt - Eng. Fan Countershaft .....	H79235	<b>♣9590HD</b>
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	<b>C152</b>
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	<b>③C83</b>
Belt - Propulsion - Upper .....	AH21301	<b>②D100</b>
Belt - Rotary Deflector .....	H86039	<b>6870</b>
Belt - Straw Chopper - Rear .....	H79789	<b>C225</b>
Belt - Straw Spreader .....	H26858	<b>B142</b>
Belt - Tailings - Lower Auger .....	N110085	<b>C128</b>
Belt - U-Joint Loading Auger .....	H23950	<b>CX120</b>
Belt - Unloader Auger Countershaft .....	H76150	<b>C60</b>
Hose - Upper .....		<b>●26511</b>
Hose - By Pass .....		<b>24224</b>
<b>1974</b>		
Belt - Alt. & W.P. ....	H80896	<b>♣9560HD</b>
Belt - Charge Pump; W/Hydro. Drive .....	T199T	<b>7400</b>
Belt - Clean Grain Elevator .....	H77766	<b>C152</b>
Belt - Clean Grain Elevator Countershaft .....	H27433	<b>C90</b>
Belt - Cyl.; W/280-845 R.P.M. ....	AH80500	<b>③69100</b>
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	<b>③B102</b>
Belt - Eng. Fan .....	H86272	<b>♣9670HD</b>
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	<b>♣9465HD</b>
Belt - Eng. Fan Countershaft .....	H79235	<b>♣9590HD</b>
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	<b>C152</b>
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	<b>③C83</b>
Belt - Propulsion - Upper .....	AH21301	<b>②D100</b>
Belt - Rotary Deflector .....	H86039	<b>6870</b>
Belt - Straw Chopper - Rear .....	H79789	<b>C225</b>
Belt - Straw Spreader .....	H26858	<b>B142</b>
Belt - Tailings - Lower Auger .....	N110085	<b>C128</b>
Belt - U-Joint Loading Auger .....	H23950	<b>CX120</b>
Belt - Unloader Auger Countershaft .....	H76150	<b>C60</b>
Hose - Upper .....		<b>●26511</b>
Hose - By Pass .....		<b>24224</b>
<b>1973</b>		
Belt - A.C. ....	H80896	<b>♣9560HD</b>
Belt - Alt. & W.P.; W/50 3/8" Belt O.C. ....	H80897	<b>♣9500HD</b>
Belt - Alt. & W.P.; W/56 3/8" Belt O.C. ....	H80896	<b>♣9560HD</b>
Belt - Charge Pump; W/Hydro. Drive .....	T199T	<b>7400</b>
Belt - Clean Grain Elevator .....	H77766	<b>C152</b>
Belt - Clean Grain Elevator Countershaft .....	H27433	<b>C90</b>
Belt - Cyl.; W/280-845 R.P.M. ....	AH80500	<b>③69100</b>
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	<b>③B102</b>
Belt - Eng. Fan; W/65 3/8" Belt O.C. ....	H86271	<b>♣9650HD</b>
Belt - Eng. Fan; W/67 3/8" Belt O.C. ....	H86272	<b>♣9670HD</b>
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	<b>♣9465HD</b>
Belt - Eng. Fan Countershaft .....	H79235	<b>♣9590HD</b>
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	<b>C152</b>
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	<b>③C83</b>
Belt - Propulsion - Upper .....	AH21301	<b>②D100</b>

②Two Required ③Three Required ●Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6600 – Continued</b>		
<b>John Deere 6-Cyl. 329 – Continued</b>		
<b>1973 – Continued</b>		
Belt - Rotary Deflector .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
Hose - Upper .....		●26511
Hose - By Pass .....		24224
<b>1972</b>		
Belt - A.C. ....	H80896	▲9560HD
Belt - Alt. & W.P.; W/50 3/8" Belt O.C. ....	H80897	▲9500HD
Belt - Alt. & W.P.; W/56 3/8" Belt O.C. ....	H80896	▲9560HD
Belt - Charge Pump; Ser. No. 9582 & Before; W/Hydro. Drive .....	T12042	7410
Belt - Charge Pump; Ser. No. 9583 & After; W/Hydro. Drive .....	T199T	7400
Belt - Charge Pump; W/Hydro. Drive .....	T12042	7410
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan; W/65 3/8" Belt O.C. ....	H86271	▲9650HD
Belt - Eng. Fan; W/67 3/8" Belt O.C. ....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Eng. Fan Countershaft .....	H79235	▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
Hose - Upper .....		●26511
Hose - By Pass .....		24224
<b>1971</b>		
Belt - A.C. ....	H80896	▲9560HD
Belt - Alt. & W.P.; W/50 3/8" Belt O.C. ....	H80897	▲9500HD
Belt - Alt. & W.P.; W/56 3/8" Belt O.C. ....	H80896	▲9560HD
Belt - Charge Pump; W/Hydro. Drive .....	T12042	7410
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan; W/65 3/8" Belt O.C. ....	H86271	▲9650HD
Belt - Eng. Fan; W/67 3/8" Belt O.C. ....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Eng. Fan Countershaft .....	H79235	▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
Hose - Upper .....		●26511
Hose - By Pass .....		24224
<b>1970</b>		
Belt - A.C. ....	H80896	▲9560HD
Belt - Alt. & W.P.; W/50 3/8" Belt O.C. ....	H80897	▲9500HD
Belt - Alt. & W.P.; W/56 3/8" Belt O.C. ....	H80896	▲9560HD
Belt - Charge Pump; W/Hydro. Drive .....	T12042	7410
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan; W/65 3/8" Belt O.C. ....	H86271	▲9650HD
Belt - Eng. Fan; W/67 3/8" Belt O.C. ....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Eng. Fan Countershaft .....	H79235	▲9590HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6600 – Continued</b>		
<b>John Deere 6-Cyl. 329 – Continued</b>		
<b>1970 – Continued</b>		
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector; Ser. No. 2252 Thru 105800 .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
Hose - Upper .....		●26511
Hose - By Pass .....		24224
<b>John Deere 6-Cyl. 329 Diesel</b>		
<b>1978</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P. ....	H82724	▲9570HD
Belt - Charge Pump; W/Hydro. Drive .....	T199T	7400
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan .....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper; Exc. Sidehill .....	AH21301	②D100
Belt - Propulsion - Upper; Ser. No. 305672 & Before; Sidehill .....	AH21301	②D100
Belt - Rotary Deflector .....	H86039	6870
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft; Exc. Sidehill .....	H76150	C60
Belt - Unloader Auger Countershaft; Ser. No. 305672 & Before; Sidehill .....	H76150	C60
<b>1977</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P. ....	H82724	▲9570HD
Belt - Charge Pump; W/Hydro. Drive .....	T199T	7400
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan .....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86039	6870
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
<b>1976</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P.; Ser. No. 208510 & Before ..	H80896	▲9560HD
Belt - Alt. & W.P.; Ser. No. 208511 & After ....	H82724	▲9570HD
Belt - Charge Pump; W/Hydro. Drive .....	T199T	7400
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan .....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86039	6870

②Two Required ③Three Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6600 – Continued</b>		
<b>John Deere 6-Cyl. 329 Diesel – Continued</b>		
<b>1976 – Continued</b>		
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
<b>1975</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P. ....	H80896	▲9560HD
Belt - Charge Pump; W/Hydro. Drive .....	T199T	7400
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan .....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86039	6870
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
<b>1974</b>		
Belt - Alt. & W.P. ....	H80896	▲9560HD
Belt - Charge Pump; W/Hydro. Drive .....	T199T	7400
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan .....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86039	6870
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
<b>1973</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P. ....	H80896	▲9560HD
Belt - Charge Pump; W/Hydro. Drive .....	T199T	7400
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan; W/65 3/8" Belt O.C. ....	H86271	▲9650HD
Belt - Eng. Fan; W/67 3/8" Belt O.C. ....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
<b>1972</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P. ....	H80896	▲9560HD
Belt - Charge Pump; Ser. No. 9582 & Before; W/Hydro. Drive .....	T12042	7410
Belt - Charge Pump; Ser. No. 9583 & After; W/Hydro. Drive .....	T199T	7400
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6600 – Continued</b>		
<b>John Deere 6-Cyl. 329 Diesel – Continued</b>		
<b>1972 – Continued</b>		
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan; W/65 3/8" Belt O.C. ....	H86271	▲9650HD
Belt - Eng. Fan; W/67 3/8" Belt O.C. ....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
<b>1971</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P. ....	H80896	▲9560HD
Belt - Charge Pump; W/Hydro. Drive .....	T12042	7410
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan; W/65 3/8" Belt O.C. ....	H86271	▲9650HD
Belt - Eng. Fan; W/67 3/8" Belt O.C. ....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
<b>1970</b>		
Belt - A.C. ....	H86275	▲9485HD
Belt - Alt. & W.P. ....	H80896	▲9560HD
Belt - Charge Pump; W/Hydro. Drive .....	T12042	7410
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan; W/65 3/8" Belt O.C. ....	H86271	▲9650HD
Belt - Eng. Fan; W/67 3/8" Belt O.C. ....	H86272	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H86274	▲9465HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector; Ser. No. 2252 Thru 105800 .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
<b>John Deere 6-Cyl. 404 Diesel</b>		
<b>1978</b>		
Belt - A.C.; Exc. Sidehill .....	H87459	▲9395HD
Belt - A.C.; Ser. No. 305672 & Before; Sidehill .....	H87459	▲9395HD
Belt - A.C.; Ser. No. 305673 & After; Sidehill ..	RT1603	▲9415HD
Belt - Alt. & W.P.; Exc. Sidehill .....	H85377	▲9610HD
Belt - Alt. & W.P.; Ser. No. 305672 & Before; Sidehill .....	H85377	▲9610HD
Belt - Alt. & W.P.; Ser. No. 305673 & After; Sidehill .....	H79236	▲9635HD
Belt - Charge Pump; W/Hydro. Drive .....	T199T	7400
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan .....	H86271	▲9650HD

②Two Required ③Three Required ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6600 - Continued</b>		
<b>John Deere 6-Cyl. 404 Diesel - Continued</b>		
<b>1978 - Continued</b>		
Belt - Eng. Fan & Rotary Screen Driveshaft; Exc. Sidehill .....	H137207	▲9500HD
Belt - Eng. Fan & Rotary Screen Driveshaft; Ser. No. 305672 & Before; Sidehill .....	H137207	▲9500HD
Belt - Eng. Fan & Rotary Screen Driveshaft; Ser. No. 305673 & After; Sidehill .....	H86273	▲9510HD
Belt - Eng. Fan Countershaft .....	H85377	▲9610HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper; Exc. Sidehill .....	AH21301	②D100
Belt - Propulsion - Upper; Ser. No. 305672 & Before; Sidehill .....	AH21301	②D100
Belt - Rotary Deflector .....	H86039	6870
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft; Exc. Sidehill .....	H76150	C60
Belt - Unloader Auger Countershaft; Ser. No. 305672 & Before; Sidehill .....	H76150	C60
Hose - Upper .....		●26511
Hose - By Pass .....		24224
<b>1977-1974</b>		
Belt - A.C. ....	H87459	▲9395HD
Belt - Alt. & W.P. ....	H85377	▲9610HD
Belt - Charge Pump; W/Hydro. Drive .....	T199T	7400
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H137207	▲9500HD
Belt - Eng. Fan Countershaft .....	H85377	▲9610HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86039	6870
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
Hose - Upper .....		●26511
Hose - By Pass .....		24224
<b>1973</b>		
Belt - A.C. ....	H87459	▲9395HD
Belt - Alt. & W.P. ....	H85377	▲9610HD
Belt - Charge Pump; W/Hydro. Drive .....	T199T	7400
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H137207	▲9500HD
Belt - Eng. Fan Countershaft .....	H79235	▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
Hose - Upper .....		●26511
Hose - By Pass .....		24224
<b>1972</b>		
Belt - A.C. ....	H87459	▲9395HD
Belt - Alt. & W.P. ....	H85377	▲9610HD
Belt - Charge Pump; Ser. No. 9582 & Before; W/Hydro. Drive .....	T12042	7410

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6600 - Continued</b>		
<b>John Deere 6-Cyl. 404 Diesel - Continued</b>		
<b>1972 - Continued</b>		
Belt - Charge Pump; Ser. No. 9583 & After; W/Hydro. Drive .....	T199T	7400
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H137207	▲9500HD
Belt - Eng. Fan Countershaft .....	H79235	▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
Hose - Upper .....		●26511
Hose - By Pass .....		24224
<b>1971</b>		
Belt - A.C. ....	H87459	▲9395HD
Belt - Alt. & W.P. ....	H85377	▲9610HD
Belt - Charge Pump; W/Hydro. Drive .....	T12042	7410
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H137207	▲9500HD
Belt - Eng. Fan Countershaft .....	H79235	▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
Hose - Upper .....		●26511
Hose - By Pass .....		24224
<b>1970</b>		
Belt - A.C. ....	H87459	▲9395HD
Belt - Alt. & W.P. ....	H85377	▲9610HD
Belt - Charge Pump; W/Hydro. Drive .....	T12042	7410
Belt - Clean Grain Elevator .....	H77766	C152
Belt - Clean Grain Elevator Countershaft .....	H27433	C90
Belt - Cyl.; W/280-845 R.P.M. ....	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M. ....	AH80503	③B102
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft ...	H137207	▲9500HD
Belt - Eng. Fan Countershaft .....	H79235	▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House .....	H77766	C152
Belt - Platform & Corn Head - Lower; Sidehill ..	AH89436	③C83
Belt - Propulsion - Upper .....	AH21301	②D100
Belt - Rotary Deflector; Ser. No. 2252 Thru 105800 .....	H86061	6876
Belt - Straw Chopper - Rear .....	H79789	C225
Belt - Straw Spreader .....	H26858	B142
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - U-Joint Loading Auger .....	H23950	CX120
Belt - Unloader Auger Countershaft .....	H76150	C60
Hose - Upper .....		●26511
Hose - By Pass .....		24224
<b>6602</b>		
<b>John Deere 6-Cyl. 404 Diesel</b>		
<b>1979-1971</b>		
Belt - A.C. ....	R46098	▲9415HD
Belt - Fan; Ser. No. 1500 & Before .....	H79237	▲9650HD
Belt - Fan; Ser. No. 1501 & After .....		▲9660HD

②Two Required ③Three Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6602 - Continued</b>		
<b>John Deere 6-Cyl. 404 Diesel - Continued</b>		
<b>1979-1971 - Continued</b>		
Belt - Fan & Countershaft; Ser. No. 1500 & Before	H79235	▲9590HD
Belt - Fan & Countershaft; Ser. No. 1501 & After	H85382	▲9600HD
Belt - W.P. & Alt.; Ser. No. 1500 & Before	H82724	▲9570HD
Belt - W.P. & Alt.; Ser. No. 1501 & After		▲9620HD
<b>6620</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
<b>1989-1988</b>		
Belt - A.C.	H113565	▲9640HD
Belt - Alt. & W.P.	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice	H101469	C72
Belt - Clean Grain Elevator & Loading Auger	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C85
Belt - Countershaft - Secondary	H110300	C150
Belt - Eng. Fan	H86272	▲9670HD
Belt - Hyd. Reel Pump	H137207	▲9500HD
Belt - Hydro. Charge Pump	T32517	7425
Belt - Regular Fixed Feeder House Conveyor Drive	H77766	C152
Belt - Rotary Screen Drive Shaft	H86273	▲9510HD
Belt - Straw Spreader	H112421	B133
Belt - Tailings Auger	H118730	C128
Belt - Unloader Auger	AH96300	②C63
<b>1987-1986</b>		
Belt - A.C.	H113565	▲9640HD
Belt - Alt. & W.P.	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice	H101469	C72
Belt - Clean Grain Elevator & Loading Auger	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C85
Belt - Countershaft - Secondary	H110300	C150
Belt - Eng. Fan	H86272	▲9670HD
Belt - Hyd. Reel Pump	H86275	▲9485HD
Belt - Hydro. Charge Pump	T32517	7425
Belt - Regular Fixed Feeder House Conveyor Drive	H77766	C152
Belt - Rotary Screen Drive Shaft	H86273	▲9510HD
Belt - Straw Spreader	H112421	B133
Belt - Tailings Auger	H118730	C128
Belt - Unloader Auger	AH96300	②C63
<b>1985</b>		
Belt - A.C.	H113565	▲9640HD
Belt - Alt. & W.P.	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice	H101469	C72
Belt - Clean Grain Elevator & Loading Auger	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C85
Belt - Countershaft - Secondary	H110300	C150
Belt - Eng. Fan	H86272	▲9670HD
Belt - Hyd. Reel Pump	H86275	▲9485HD
Belt - Hydro. Charge Pump	T32517	7425
Belt - Regular Feeder House - Lower	H111519	D158
Belt - Regular Fixed Feeder House Conveyor Drive	H77766	C152
Belt - Rotary Screen Drive Shaft	H86273	▲9510HD
Belt - Straw Spreader	H112421	B133
Belt - Tailings Auger	H118730	C128
Belt - Unloader Auger	AH96300	②C63
<b>1984</b>		
Belt - A.C.	H113565	▲9640HD
Belt - Alt. & W.P.	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice	H101469	C72
Belt - Clean Grain Elevator & Loading Auger	H77766	C152

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6620 - Continued</b>		
<b>John Deere 6-Cyl. 466 Diesel - Continued</b>		
<b>1984 - Continued</b>		
Belt - Clean Grain Elevator Countershaft	H27433	C85
Belt - Countershaft - Secondary	H110300	C150
Belt - Eng. Fan	H86272	▲9670HD
Belt - Feeder House - Lower; Sidehill	AH89436	②C83
Belt - Hyd. Reel Pump	H86275	▲9485HD
Belt - Hydro. Charge Pump	T199T	7400
Belt - Regular Feeder House - Lower	H111519	D158
Belt - Regular Fixed Feeder House Conveyor Drive	H77766	C152
Belt - Rotary Screen Drive Shaft	H86273	▲9510HD
Belt - Straw Spreader	H112421	B133
Belt - Tailings Auger	H118730	C128
Belt - Unloader Auger	AH96300	②C63
<b>1983</b>		
Belt - A.C.	R71603	▲9415HD
Belt - Alt. & W.P.	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice	H101469	C72
Belt - Clean Grain Elevator & Loading Auger	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C85
Belt - Countershaft - Secondary	H110300	C150
Belt - Eng. Fan	H86272	▲9670HD
Belt - Hyd. Reel Pump	H86275	▲9485HD
Belt - Hydro. Charge Pump	T199T	7400
Belt - Regular Feeder House - Lower	H111519	D158
Belt - Regular Fixed Feeder House Conveyor Drive	H77766	C152
Belt - Rotary Screen Drive Shaft	H86273	▲9510HD
Belt - Straw Spreader	H112421	B133
Belt - Tailings Auger	H118730	C128
Belt - Unloader Auger	AH96300	②C63
<b>1982</b>		
Belt - A.C.	R71603	▲9415HD
Belt - Alt. & W.P.	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice	H101469	C72
Belt - Clean Grain Elevator & Loading Auger	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C85
Belt - Eng. Fan	H86272	▲9670HD
Belt - Hyd. Reel Pump	H86275	▲9485HD
Belt - Hydro. Charge Pump	T199T	7400
Belt - Regular Feeder House - Lower	H111519	D158
Belt - Regular Fixed Feeder House Conveyor Drive	H77766	C152
Belt - Rotary Screen Drive Shaft	H86273	▲9510HD
Belt - Straw Spreader	H112421	B133
Belt - Tailings Auger	H118730	C128
Belt - Unloader Auger	AH96300	②C63
<b>1981-1979</b>		
Belt - A.C.	R71603	▲9415HD
Belt - Alt. & W.P.	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice	H101469	C72
Belt - Clean Grain Elevator & Loading Auger	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C85
Belt - Eng. Fan	H86272	▲9670HD
Belt - Hyd. Reel Pump	H86275	▲9485HD
Belt - Hydro. Charge Pump	T199T	7400
Belt - Rotary Screen Drive Shaft	H86273	▲9510HD
Belt - Straw Spreader	H112421	B133
Belt - Tailings Auger	H118730	C128
Belt - Unloader Auger	AH96300	②C63
<b>6622</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
<b>1985-1980</b>		
Belt - A.C.	R71603	▲9415HD
Belt - Fan & Hyd. Pump	H86272	▲9670HD
Belt - W.P. & Alt.	H86273	▲9510HD

②Two Required ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>7700 Combine</b>		
<b>John Deere 6-Cyl. 362</b>		
<b>1978-1974</b>		
Belt - Alt. & W.P.	H80896	▲9560HD
Belt - Charge Pump; W/Hydro. Drive	T199T	7400
Belt - Clean Grain Elevator Countershaft	H27433	C90
Belt - Eng. Fan	H86271	▲9650HD
Belt - Feeder Conveyor; W/Regular Feeder House	H77766	C152
Belt - Rotary Deflector	H86039	6870
Belt - Straw Chopper - Rear	H79789	C225
Belt - Straw Spreader	H26858	B142
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Belt - Unloader Auger Countershaft	H76150	C60
<b>1973</b>		
Belt - A.C.	H80897	▲9500HD
Belt - Alt. & W.P.	H80896	▲9560HD
Belt - Charge Pump; W/Hydro. Drive	T199T	7400
Belt - Clean Grain Elevator Countershaft	H27433	C90
Belt - Eng. Fan	H86271	▲9650HD
Belt - Eng. Fan Countershaft	H79235	▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House	H77766	C152
Belt - Rotary Deflector	H86061	6876
Belt - Straw Chopper - Rear	H79789	C225
Belt - Straw Spreader	H26858	B142
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Belt - Unloader Auger Countershaft	H76150	C60
<b>1972</b>		
Belt - A.C.	H80897	▲9500HD
Belt - Alt. & W.P.	H80896	▲9560HD
Belt - Charge Pump; W/Hydro. Drive; Ser. No. 6207 & Before	T12042	7410
Belt - Charge Pump; W/Hydro. Drive; Ser. No. 6208 & After	T199T	7400
Belt - Charge Pump; W/Power RWD; Ser. No. 6207 & Before	T199T	7400
Belt - Clean Grain Elevator Countershaft	H27433	C90
Belt - Cyl.; W/280-845 R.P.M.	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M.	AH80503	③B102
Belt - Eng. Fan	H86271	▲9650HD
Belt - Eng. Fan Countershaft	H79235	▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House	H77766	C152
Belt - Rotary Deflector	H86061	6876
Belt - Straw Chopper - Rear	H79789	C225
Belt - Straw Spreader	H26858	B142
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Belt - Unloader Auger Countershaft	H76150	C60
<b>1971</b>		
Belt - A.C.	H80897	▲9500HD
Belt - Alt. & W.P.	H80896	▲9560HD
Belt - Charge Pump; W/Hydro. Drive	T12042	7410
Belt - Charge Pump; W/Power RWD	T199T	7400
Belt - Clean Grain Elevator Countershaft	H27433	C90
Belt - Cyl.; W/280-845 R.P.M.	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M.	AH80503	③B102
Belt - Eng. Fan	H86271	▲9650HD
Belt - Eng. Fan Countershaft	H79235	▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House	H77766	C152
Belt - Rotary Deflector	H86061	6876
Belt - Straw Chopper - Rear	H79789	C225
Belt - Straw Spreader	H26858	B142
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Belt - Unloader Auger Countershaft	H76150	C60
<b>1970</b>		
Belt - A.C.	H80897	▲9500HD
Belt - Alt. & W.P.	AR41628	②7555
Belt - Charge Pump; W/Hydro. Drive	T12042	7410
Belt - Charge Pump; W/Power RWD	T199T	7400
Belt - Clean Grain Elevator Countershaft	H27433	C90
Belt - Cyl.; W/280-845 R.P.M.	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M.	AH80503	③B102

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>7700 Combine - Continued</b>		
<b>John Deere 6-Cyl. 362 - Continued</b>		
<b>1970 - Continued</b>		
Belt - Eng. Fan	H86271	▲9650HD
Belt - Eng. Fan Countershaft	H79235	▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House	H77766	C152
Belt - Rotary Deflector; Ser. No. 1278 Thru 111900	H86061	6876
Belt - Straw Chopper - Rear	H79789	C225
Belt - Straw Spreader	H26858	B142
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Belt - Unloader Auger Countershaft	H76150	C60
<b>John Deere 6-Cyl. 404 Diesel</b>		
<b>1978-1975</b>		
Belt - A.C.; W/O Turbo	H87459	▲9395HD
Belt - A.C.; W/Turbo	R71603	▲9415HD
Belt - Alt. & W.P.; W/O Turbo	H85377	▲9610HD
Belt - Alt. & W.P.; W/Turbo; W/63 3/8" Belt O.C.	R70871	▲9630HD
Belt - Alt. & W.P.; W/Turbo; W/63 7/8" Belt O.C.	H79236	▲9635HD
Belt - Charge Pump; W/Hydro. Drive	T199T	7400
Belt - Clean Grain Elevator	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C90
Belt - Eng. Fan	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft; W/O Turbo	H137207	▲9500HD
Belt - Eng. Fan & Rotary Screen Driveshaft; W/Turbo	H86273	▲9510HD
Belt - Feeder Conveyor; W/Regular Feeder House	H77766	C152
Belt - Propulsion - Upper; W/O Turbo	AH21301	②D100
Belt - Rotary Deflector	H86039	6870
Belt - Straw Chopper - Rear	H79789	C225
Belt - Straw Spreader	H26858	B142
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Belt - Unloader Auger Countershaft; W/O Turbo	H76150	C60
Hose - Upper - Eng. To Pipe		⌘-20431
Hose - Upper - Pipe To Rad.		⌘-20685
Hose - Lower - Eng. To Pipe		⌘-20431
Hose - Lower - Pipe To Rad.		⌘-20206
<b>1974</b>		
Belt - A.C.; W/O Turbo	H81742	▲9530HD
Belt - A.C.; W/Turbo	H80896	▲9560HD
Belt - Alt. & W.P.; W/O Turbo	R52507	▲9610HD
Belt - Alt. & W.P.; W/Turbo; W/62 7/8" Belt O.C.	R52603	▲9625HD
Belt - Alt. & W.P.; W/Turbo; W/63 3/8" Belt O.C.	R70871	▲9630HD
Belt - Charge Pump; W/Hydro. Drive	T199T	7400
Belt - Clean Grain Elevator	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C90
Belt - Eng. Fan	H86271	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft; W/O Turbo	H137207	▲9500HD
Belt - Eng. Fan & Rotary Screen Driveshaft; W/Turbo	H86273	▲9510HD
Belt - Feeder Conveyor; W/Regular Feeder House	H77766	C152
Belt - Propulsion - Upper; W/O Turbo	AH21301	②D100
Belt - Rotary Deflector	H86039	6870
Belt - Straw Chopper - Rear	H79789	C225
Belt - Straw Spreader	H26858	B142
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Belt - Unloader Auger Countershaft; W/O Turbo	H76150	C60
Hose - Upper - Eng. To Pipe		⌘-20431
Hose - Upper - Pipe To Rad.		⌘-20685
Hose - Lower - Eng. To Pipe		⌘-20431
Hose - Lower - Pipe To Rad.		⌘-20206
<b>1973</b>		
Belt - A.C.; W/O Turbo	H81742	▲9530HD
Belt - A.C.; W/Turbo	H80896	▲9560HD

②Two Required ③Three Required ⌘Cut to Fit ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>7700 Combine – Continued</b>		
<b>John Deere 6–Cyl. 404 Diesel – Continued</b>		
<b>1973 – Continued</b>		
Belt - Alt. & W.P.; W/O Turbo	R52507	▲9610HD
Belt - Alt. & W.P.; W/Turbo; W/62 7/8" Belt O.C.	R52603	▲9625HD
Belt - Alt. & W.P.; W/Turbo; W/63 3/8" Belt O.C.	R70871	▲9630HD
Belt - Charge Pump; W/Hydro. Drive	T199T	7400
Belt - Clean Grain Elevator	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C90
Belt - Eng. Fan	H84740	▲9670HD
Belt - Eng. Fan & Rotary Screen Driveshaft; W/O Turbo	H137207	▲9500HD
Belt - Eng. Fan & Rotary Screen Driveshaft; W/Turbo	H86273	▲9510HD
Belt - Eng. Fan Countershaft; W/O Turbo	H85377	▲9610HD
Belt - Eng. Fan Countershaft; W/Turbo	H84745	▲9620HD
Belt - Feeder Conveyor; W/Regular Feeder House	H77766	C152
Belt - Propulsion - Upper; W/O Turbo	AH21301	②D100
Belt - Rotary Deflector	H86061	6876
Belt - Straw Chopper - Rear	H79789	C225
Belt - Straw Spreader	H26858	B142
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Belt - Unloader Auger Countershaft; W/O Turbo	H76150	C60
Hose - Upper - Eng. To Pipe	≈<20431	
Hose - Upper - Pipe To Rad.	≈<20685	
Hose - Lower - Eng. To Pipe	≈<20431	
Hose - Lower - Pipe To Rad.	≈<20206	
<b>1972</b>		
Belt - A.C.; W/O Turbo	H80897	▲9500HD
Belt - Alt. & W.P.; W/57 3/8" Belt O.C.	H82724	▲9570HD
Belt - Alt. & W.P.; W/Turbo; W/63 3/8" Belt O.C.	R70871	▲9630HD
Belt - Charge Pump; W/Hydro. Drive; Ser. No. 6207 & Before	T12042	7410
Belt - Charge Pump; W/Hydro. Drive; Ser. No. 6208 & After	T199T	7400
Belt - Charge Pump; W/Power RWD; Ser. No. 6207 & Before	T199T	7400
Belt - Clean Grain Elevator	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C90
Belt - Cyl.; W/280-845 R.P.M.	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M.	AH80503	③B102
Belt - Eng. Fan; W/O Turbo	H79237	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft; W/O Turbo	H137207	▲9500HD
Belt - Eng. Fan & Rotary Screen Driveshaft; W/Turbo	H86273	▲9510HD
Belt - Eng. Fan Countershaft; W/O Turbo	H79235	②▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House	H77766	C152
Belt - Propulsion - Upper; W/O Turbo	AH21301	②D100
Belt - Rotary Deflector	H86061	6876
Belt - Straw Chopper - Rear	H79789	C225
Belt - Straw Spreader	H26858	B142
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Hose - Upper - Eng. To Pipe	≈<20431	
Hose - Upper - Pipe To Rad.	≈<20685	
Hose - Lower - Eng. To Pipe	≈<20431	
Hose - Lower - Pipe To Rad.	≈<20206	
<b>1971</b>		
Belt - A.C.; W/O Turbo	H80897	▲9500HD
Belt - Alt. & W.P.; W/57 3/8" Belt O.C.	H82724	▲9570HD
Belt - Alt. & W.P.; W/Turbo; W/63 3/8" Belt O.C.	R70871	▲9630HD
Belt - Charge Pump; W/Hydro. Drive	T12042	7410
Belt - Charge Pump; W/Power RWD	T199T	7400
Belt - Clean Grain Elevator	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C90
Belt - Cyl.; W/280-845 R.P.M.	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M.	AH80503	③B102
Belt - Eng. Fan; W/O Turbo	H79237	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft; W/O Turbo	H137207	▲9500HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>7700 Combine – Continued</b>		
<b>John Deere 6–Cyl. 404 Diesel – Continued</b>		
<b>1971 – Continued</b>		
Belt - Eng. Fan & Rotary Screen Driveshaft; W/Turbo	H86273	▲9510HD
Belt - Eng. Fan Countershaft; W/O Turbo	H79235	②▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House	H77766	C152
Belt - Propulsion - Upper; W/O Turbo	AH21301	②D100
Belt - Rotary Deflector	H86061	6876
Belt - Straw Chopper - Rear	H79789	C225
Belt - Straw Spreader	H26858	B142
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Hose - Upper - Eng. To Pipe	≈<20431	
Hose - Upper - Pipe To Rad.	≈<20685	
Hose - Lower - Eng. To Pipe	≈<20431	
Hose - Lower - Pipe To Rad.	≈<20206	
<b>1970</b>		
Belt - A.C.; W/O Turbo	H80897	▲9500HD
Belt - Alt. & W.P.; W/57 5/8" Belt O.C.	AR41629	②7570
Belt - Alt. & W.P.; W/Turbo; W/63 3/8" Belt O.C.	R70871	▲9630HD
Belt - Charge Pump; W/Hydro. Drive	T12042	7410
Belt - Charge Pump; W/Power RWD	T199T	7400
Belt - Clean Grain Elevator	H77766	C152
Belt - Clean Grain Elevator Countershaft	H27433	C90
Belt - Cyl.; W/280-845 R.P.M.	AH80505	③69100
Belt - Cyl.; W/407-1228 R.P.M.	AH80503	③B102
Belt - Eng. Fan	H79237	▲9650HD
Belt - Eng. Fan & Rotary Screen Driveshaft; W/O Turbo	H137207	▲9500HD
Belt - Eng. Fan & Rotary Screen Driveshaft; W/Turbo	H86273	▲9510HD
Belt - Eng. Fan Countershaft; W/O Turbo	H79235	②▲9590HD
Belt - Feeder Conveyor; W/Regular Feeder House	H77766	C152
Belt - Propulsion - Upper; W/O Turbo	AH21301	②D100
Belt - Rotary Deflector; Ser. No. 1278 Thru 111900	H86061	6876
Belt - Straw Chopper - Rear	H79789	C225
Belt - Straw Spreader	H26858	B142
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Hose - Upper - Eng. To Pipe	≈<20431	
Hose - Upper - Pipe To Rad.	≈<20685	
Hose - Lower - Eng. To Pipe	≈<20431	
Hose - Lower - Pipe To Rad.	≈<20206	
<b>7720</b>		
<b>John Deere 6–Cyl. 466 Diesel</b>		
<b>1989–1988</b>		
Belt - A.C.	H113565	▲9640HD
Belt - Alt. & W.P.	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice	H101469	C72
Belt - Countershaft - Secondary	H110300	C150
Belt - Eng. Fan	H86271	▲9650HD
Belt - Hyd. Reel Pump	H137207	▲9500HD
Belt - Hydro. Charge Pump	T32517	7425
Belt - Regular Feeder House - Lower	H111519	D158
Belt - Regular Fixed Feeder House Conveyor Drive	H77766	C152
Belt - Rotary Screen Drive Shaft	H86273	▲9510HD
Belt - Straw Spreader	H112421	B133
Belt - Unloader Auger	AH96300	②C63
<b>1987–1984</b>		
Belt - A.C.	H113565	▲9640HD
Belt - Alt. & W.P.	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice	H101469	C72
Belt - Countershaft - Secondary	H110300	C150
Belt - Eng. Fan	H86271	▲9650HD
Belt - Hyd. Reel Pump	H86275	▲9485HD
Belt - Hydro. Charge Pump	T32517	7425

②Two Required ③Three Required ≈<Cut to Fit ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>7720 - Continued</b>		
<b>John Deere 6-Cyl. 466 Diesel - Continued</b>		
<b>1987-1984 - Continued</b>		
Belt - Regular Feeder House - Lower .....	H111519	D158
Belt - Regular Fixed Feeder House Conveyor Drive .....	H77766	C152
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>1983</b>		
Belt - A.C. ....	R71603	▲9415HD
Belt - Alt. & W.P. ....	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72
Belt - Countershaft - Secondary .....	H110300	C150
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Hyd. Reel Pump .....	H86275	▲9485HD
Belt - Hydro. Charge Pump .....	T32517	7425
Belt - Regular Feeder House - Lower .....	H111519	D158
Belt - Regular Fixed Feeder House Conveyor Drive .....	H77766	C152
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>1982</b>		
Belt - A.C. ....	R71603	▲9415HD
Belt - Alt. & W.P. ....	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Hyd. Reel Pump .....	H86275	▲9485HD
Belt - Hydro. Charge Pump .....	T199T	7400
Belt - Regular Feeder House - Lower .....	H111519	D158
Belt - Regular Fixed Feeder House Conveyor Drive .....	H77766	C152
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>1981-1979</b>		
Belt - A.C. ....	R71603	▲9415HD
Belt - Alt. & W.P. ....	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72
Belt - Eng. Fan .....	H86271	▲9650HD
Belt - Hyd. Reel Pump .....	H86275	▲9485HD
Belt - Hydro. Charge Pump .....	T199T	7400
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>8820</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
<b>1989</b>		
Belt - A.C. ....	H122189	▲9420HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72
Belt - Clean Grain Elevator Countershaft .....	H27433	C85
Belt - Countershaft - Secondary .....	H110300	C150
Belt - Fan & Hyd. Pump .....	AH96333	②69100
Belt - Hyd. Reel Pump .....	H137207	▲9500HD
Belt - Hydro. Charge Pump .....	T32517	7425
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>1988</b>		
Belt - A.C. ....	H122189	▲9420HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72

②Two Required ▲Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>8820 - Continued</b>		
<b>John Deere 6-Cyl. 466 Diesel - Continued</b>		
<b>1988 - Continued</b>		
Belt - Countershaft - Secondary .....	H110300	C150
Belt - Fan & Hyd. Pump .....	AH96333	②69100
Belt - Hyd. Reel Pump .....	H137207	▲9500HD
Belt - Hydro. Charge Pump .....	T32517	7425
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>1987</b>		
Belt - A.C. ....	H122189	▲9420HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72
Belt - Countershaft - Secondary .....	H110300	C150
Belt - Fan & Hyd. Pump .....	AH96333	②69100
Belt - Hyd. Reel Pump .....	H86275	▲9485HD
Belt - Hydro. Charge Pump .....	T32517	7425
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>1986</b>		
Belt - A.C. ....	H122189	▲9420HD
Belt - Alt. & W.P. ....	H86271	▲9650HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72
Belt - Countershaft - Secondary .....	H110300	C150
Belt - Fan & Hyd. Pump .....	AH96333	②69100
Belt - Hyd. Reel Pump .....	H86275	▲9485HD
Belt - Hydro. Charge Pump .....	T32517	7425
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>1985-1983</b>		
Belt - A.C. ....	R71603	▲9415HD
Belt - Alt. & W.P. ....	H86271	▲9650HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72
Belt - Countershaft - Secondary .....	H110300	C150
Belt - Fan & Hyd. Pump .....	AH96333	②69100
Belt - Hyd. Reel Pump .....	H86275	▲9485HD
Belt - Hydro. Charge Pump .....	T32517	7425
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>1982</b>		
Belt - A.C. ....	R71603	▲9415HD
Belt - Alt. & W.P. ....	H86271	▲9650HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72
Belt - Countershaft - Secondary; Ser. No. 556101 & After .....	H110300	C150
Belt - Fan & Hyd. Pump .....	AH96333	②69100
Belt - Hyd. Reel Pump .....	H86275	▲9485HD
Belt - Hydro. Charge Pump .....	T32517	7425
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>1981</b>		
Belt - A.C. ....	R71603	▲9415HD
Belt - Alt. & W.P. ....	H86271	▲9650HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72
Belt - Fan & Hyd. Pump .....	AH96333	②69100
Belt - Hyd. Reel Pump .....	H86275	▲9485HD
Belt - Hydro. Charge Pump .....	T32517	7425
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133

Agricultural Equipment



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>8820 – Continued</b>		
<b>John Deere 6–Cyl. 466 Diesel – Continued</b>		
<b>1981 – Continued</b>		
Belt - Unloader Auger .....	AH96300	②C63
<b>1980</b>		
Belt - A.C.; Ser. No. 414851 Thru 415847 .....	R69562	▲9415HD
Belt - Alt. & W.P. ....	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72
Belt - Fan & Hyd. Pump .....	AH96333	②69100
Belt - Hyd. Reel Pump .....	H86275	▲9485HD
Belt - Hydro. Charge Pump .....	T32517	7425
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>1979</b>		
Belt - A.C. ....	R46098	▲9415HD
Belt - Alt. & W.P. ....	H79236	▲9635HD
Belt - Beater Drive; W/100 Percent Beater Speed; Corn, Bean .....	H96414	C68
Belt - Beater Drive; W/150 Percent Beater Speed; Grain, Rice .....	H101469	C72
Belt - Fan & Hyd. Pump .....	AH96333	②69100
Belt - Hyd. Reel Pump .....	H86275	▲9485HD
Belt - Hydro. Charge Pump .....	T32517	7425
Belt - Rotary Screen Drive Shaft .....	H86273	▲9510HD
Belt - Straw Spreader .....	H112421	B133
Belt - Unloader Auger .....	AH96300	②C63
<b>9400 Combine</b>		
<b>John Deere 6068T Powertech Diesel</b>		
<b>1997–1993</b>		
Belt - A.C. ....	H80896	▲9560HD
Belt - Alt. ....	H101813	▲9580HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	E46113	C83
Belt - Cooling Fan; W/High Power Fan .....	H132808	B53
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Spreader .....	Z33774	B77
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH127866	②C90
<b>1992</b>		
Belt - A.C. ....	H101813	▲9580HD
Belt - Alt. ....	H101813	▲9580HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	E46113	C83
Belt - Cooling Fan; W/High Power Fan .....	H132808	B53
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Spreader .....	Z33774	B77
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH127866	②C90
<b>1991</b>		
Belt - A.C. ....	H101813	▲9580HD
Belt - Alt. ....	H101813	▲9580HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	E46113	C83
Belt - Cooling Fan; W/High Power Fan .....	H132808	B53
Belt - Rotary Screen Drive Shaft; Ser. No. 640506 & After .....	H146636	XPA1000
Belt - Straw Spreader .....	Z33774	B77
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH127866	②C90
<b>1990</b>		
Belt - A.C. ....	H134772	▲9570HD
Belt - Alt. ....	H101813	▲9580HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	E46113	C83

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9400 Combine – Continued</b>		
<b>John Deere 6068T Powertech Diesel – Continued</b>		
<b>1990 – Continued</b>		
Belt - Clean Grain Elevator .....	H137830	C315
Belt - Cooling Fan; W/High Power Fan .....	H132808	B53
Belt - Straw Spreader .....	Z33774	B77
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH127866	②C90
<b>1989</b>		
Belt - A.C. ....	H134772	▲9570HD
Belt - Alt. ....	RE44538	②▲9580HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	E46113	C83
Belt - Clean Grain Elevator .....	H137830	C315
Belt - Cooling Fan; W/High Power Fan .....	H132808	B53
Belt - Straw Spreader .....	Z33774	B77
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH127866	②C90
<b>9410</b>		
<b>John Deere 6–Cyl. 6.8 L Diesel</b>		
<b>1999</b>		
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	E46113	C83
Belt - Cooling Fan .....	H132808	B53
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Spreader .....	Z33774	B77
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - Unloading System .....	AH158880	C90
<b>1998</b>		
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	E46113	C83
Belt - Cooling Fan .....	H132808	B53
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Spreader .....	Z33774	B77
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - Unloading System .....	AH158880	②C90
<b>9450</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2003–1999</b>		
Belt - Air Flow Fan Drive .....	H171386	B108
Belt - Alt.; W/185A. Alt. ....	R502417	▲K080830HD
Belt - Alt.; W/95A. Alt. ....	R502418	▲K080816HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Cooling Fan .....	H132808	B53
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Spreader .....	Z33774	B77
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - Unloader Drive .....	AH158880	C90
<b>9500</b>		
<b>John Deere 6–Cyl. 7.6 L Diesel</b>		
<b>1997–1996</b>		
Belt - A.C. ....	H80896	▲9560HD
Belt - Alt. ....	H101813	▲9580HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	H23950	CX120
Belt - Cooling Fan; W/Low Power Fan .....	H132808	B53
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH127866	②C90
Hose - By Pass .....		24232
<b>1995–1992</b>		
Belt - A.C. ....	H80896	▲9560HD
Belt - Alt.; W/High Power Alt. ....	H101813	▲9580HD
Belt - Alt.; W/Low Power Alt. ....	H134344	▲9430HD

②Two Required ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9500 – Continued</b>		
<b>John Deere 6–Cyl. 7.6 L Diesel – Continued</b>		
<b>1995–1992 – Continued</b>		
Belt - Beater Drive; W/100 Percent Beater		
Speed	AH139436	②C73
Belt - Chopper - Windrow or Forward		
Position	H23950	CX120
Belt - Cooling Fan; W/Low Power Fan	H132808	B53
Belt - Rotary Screen Drive Shaft	H146636	XPA1000
Belt - Tailings - Lower Auger & Elevator	N110085	C128
Belt - Unloading System	AH127866	②C90
Hose - By Pass		24232
<b>1991</b>		
Belt - A.C.	H81742	▲9530HD
Belt - Alt.; W/High Power Alt.	H101813	▲9580HD
Belt - Alt.; W/Low Power Alt.	R73189	▲9430HD
Belt - Beater Drive; W/100 Percent Beater		
Speed	AH139436	②C73
Belt - Chopper - Windrow or Forward		
Position	H23950	CX120
Belt - Cooling Fan; W/Low Power Fan	H132808	B53
Belt - Rotary Screen Drive Shaft; Ser. No. 642579 & After	H146636	XPA1000
Belt - Tailings - Lower Auger & Elevator	N110085	C128
Belt - Unloading System	AH127866	②C90
Hose - By Pass		24232
<b>1990</b>		
Belt - A.C.	H81742	▲9530HD
Belt - Alt.; W/High Power Alt.	H101813	▲9580HD
Belt - Alt.; W/Low Power Alt.	H134344	▲9430HD
Belt - Beater Drive; W/100 Percent Beater		
Speed	AH139436	②C73
Belt - Chopper - Windrow or Forward		
Position	P47885	C109
Belt - Clean Grain Elevator	H137830	C315
Belt - Cooling Fan; W/Low Power Fan	H132808	B53
Belt - Tailings - Lower Auger & Elevator	N110085	C128
Belt - Unloading System	AH127866	②C90
Hose - By Pass		24232
<b>1989</b>		
Belt - A.C.	H134437	▲9580HD
Belt - Alt.	H134344	▲9430HD
Belt - Beater Drive; W/100 Percent Beater		
Speed	AH139436	②C73
Belt - Chopper - Windrow or Forward		
Position	P47885	C109
Belt - Clean Grain Elevator	H137830	C315
Belt - Cooling Fan; W/Low Power Fan	H132808	B53
Belt - Tailings - Lower Auger & Elevator	N110085	C128
Belt - Unloading System	AH127866	②C90
Hose - By Pass		24232
<b>9510</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
<b>1999</b>		
Belt - Serpentine - Alt. & A.C.	H163515	▲K080872HD
Belt - Beater Drive; W/100 Percent Beater		
Speed	AH139436	②C73
Belt - Chopper - Forward Position; W/Fine		
Cut	H22529	B120
Belt - Chopper - Windrow or Forward		
Position	H23950	CX120
Belt - Tailings - Lower Auger	N110085	C128
Belt - Unloading System	AH158880	C90
<b>1998</b>		
Belt - Serpentine - Alt. & A.C.	H163515	▲K080872HD
Belt - Beater Drive; W/100 Percent Beater		
Speed	AH139436	②C73
Belt - Chopper - Forward Position; W/Fine		
Cut	H22529	B120
Belt - Chopper - Windrow or Forward		
Position	H23950	CX120
Belt - Tailings - Lower Auger	N110085	C128
Belt - Unloading System	AH158880	C90
Tensioner Assy. - Alt.	RE68715	38507
Tensioner Pulley - Alt.	RE68715	36091

②Two Required ▲Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9510 SH</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
<b>1999</b>		
Belt - Serpentine - Alt. & A.C.	H163515	▲K080872HD
Belt - Beater Drive; W/100 Percent Beater		
Speed	AH139436	②C73
Belt - Chopper - Forward Position; W/Fine		
Cut	H22529	B120
Belt - Chopper - Windrow or Forward		
Position	H23950	CX120
Belt - Tailings - Lower Auger	N110085	C128
Belt - Unloading System	AH158880	C90
<b>1998</b>		
Belt - Serpentine - Alt. & A.C.	H163515	▲K080872HD
Belt - Beater Drive; W/100 Percent Beater		
Speed	AH139436	②C73
Belt - Chopper - Forward Position; W/Fine		
Cut	H22529	B120
Belt - Chopper - Windrow or Forward		
Position	H23950	CX120
Belt - Tailings - Lower Auger	N110085	C128
Belt - Unloading System	AH158880	C90
Tensioner Assy. - Alt.	RE68715	38507
<b>9550</b>		
<b>John Deere 6081 Powertech Diesel</b>		
<b>2003–1999</b>		
Belt - Alt.; W/185A. Alt.	H166870	▲K080878HD
Belt - Alt.; W/95A. Alt.	H163515	▲K080872HD
Belt - Beater Drive; W/100 Percent Beater		
Speed	AH139436	②C73
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
<b>9550 SH</b>		
<b>John Deere 6081 Powertech Diesel</b>		
<b>2003–2000</b>		
Belt - Alt.; W/185A. Alt.	H166870	▲K080878HD
Belt - Alt.; W/95A. Alt.	H163515	▲K080872HD
Belt - Beater Drive; W/100 Percent Beater		
Speed	AH139436	②C73
Belt - Tailings - Lower Auger	N110085	C128
Belt - U-Joint Loading Auger	H23950	CX120
Belt - Unloading System	AH158880	②C90
<b>1999</b>		
Belt - Air Flow Fan Drive	H171386	B108
Belt - Alt.; W/185A. Alt.	H166870	▲K080878HD
Belt - Alt.; W/95A. Alt.	H163515	▲K080872HD
Belt - Beater Drive; W/100 Percent Beater		
Speed	AH139436	②C73
Belt - Straw Chopper; W/Std. Cut	H160654	C170
Belt - Straw Chopper; W/Std. Cut Bailing	H23950	CX120
Belt - Tailings - Lower Auger	N110085	C128
Belt - Unloading System	AH158880	②C90
Tensioner Assy. - Fan	RE518097	38507
<b>9560 SH</b>		
<b>John Deere 6–Cyl. 6.8 L Diesel</b>		
<b>2005–2003</b>		
Belt - Serpentine - Alt.; W/200A. Alt.	R135607	▲K080785HD
Belt - Serpentine - Alt.; W/95A. Alt.	R135606	▲K080774HD
Belt - Discharge Beater	H168301	C130
Belt - Tailings Auger & Elevator; W/Edible		
Bean	AC72	C72
Tensioner Assy. - Fan	RE70536	38654
<b>9560 STS</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
<b>2007–2003</b>		
Belt - Serpentine - Alt.; W/200A. Alt.	R135607	▲K080785HD
Belt - Serpentine - Alt.; W/95A. Alt.	R135606	▲K080774HD
Belt - Discharge Beater	H168301	C130
Belt - Tailings Auger & Elevator; W/Edible		
Bean	AC72	C72
Tensioner Assy. - Fan	RE70536	38654

Agricultural Equipment





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9570 STS</b>		
<b>John Deere 6-Cyl. 6.8 L Diesel</b>		
<b>2009</b>		
Belt - Serpentine - Alt.; W/200A. Alt. ....	R521053	▲K080889HD
Belt - J.S. - Front (Right Hand); W/Edible Bean .....	AC144	C144
Belt - Tailings Auger & Elevator; W/Edible Bean .....	AC72	C72
Tensioner Assy. - Serpentine .....	RE518097	38507
<b>2008</b>		
Belt - Serpentine - Alt.; W/200A. Alt. ....	R521053	▲K080889HD
Belt - J.S. - Front (Right Hand); W/Edible Bean .....	AC144	C144
Belt - Tailings Auger & Elevator; W/Edible Bean .....	AC72	C72
Tensioner Assy. - Alt.; W/200A. Alt. ....	RE518097	38507
<b>9600</b>		
<b>John Deere 6-Cyl. 7.6 L Diesel</b>		
<b>1997-1993</b>		
Belt - A.C. ....	H80896	▲9560HD
Belt - Alt. ....	H101813	▲9580HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	H23950	CX120
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH127866	②C90
<b>1992</b>		
Belt - A.C. ....	H81742	▲9530HD
Belt - Alt. ....	H101813	▲9580HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	H23950	CX120
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH127866	②C90
<b>1991</b>		
Belt - A.C. ....	H81742	▲9530HD
Belt - Alt. ....	R73189	▲9430HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	H23950	CX120
Belt - Cooling Fan; Ser. No. 641716 & Before .....	H132808	B53
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH127866	②C90
<b>1990</b>		
Belt - A.C. ....	H81742	▲9530HD
Belt - Alt. ....	R73189	▲9430HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Beater Drive; W/75 Percent Beater Speed .....	AH131960	②C72
Belt - Chopper - Windrow or Forward Position .....	P47885	C109
Belt - Cooling Fan .....	H132808	B53
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH127866	②C90
<b>1989</b>		
Belt - A.C. ....	H134437	▲9580HD
Belt - Alt. ....	RE44538	②▲9580HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position .....	P47885	C109
Belt - Cooling Fan .....	H132808	B53
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH127866	②C90
<b>9610</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
<b>1999</b>		
Belt - Serpentine - Alt. & A.C. ....	H163515	▲K080872HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9610 - Continued</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel - Continued</b>		
<b>1999 - Continued</b>		
Belt - Beater Drive .....	AH139436	②C73
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - U-Joint Loading Auger .....	H23950	CX120
<b>1998</b>		
Belt - Serpentine - Alt. & A.C. ....	H163515	▲K080872HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Chopper - Windrow or Forward Position; W/Fine Cut .....	H22529	B120
Belt - Chopper - Windrow or Forward Position; W/Std. Cut .....	H23950	CX120
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Tailings - Lower Auger .....	N110085	C128
Belt - Unloading System .....	AH158880	C90
<b>9650</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
<b>2003-2002</b>		
Belt - Air Flow Fan Drive .....	H171386	B108
Belt - Alt.; W/185A. Alt. ....	R164820	▲K080468HD
Belt - Alt.; W/95A. Alt. ....	H163515	▲K080872HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Cooling Fan .....	H177186	▲K080910HD
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Chopper; W/Fine Cut Bailing; W/123" Belt O.C. ....	H22529	B120
Belt - Straw Chopper; W/Std. Cut Bailing; W/124" Belt O.C. ....	H23950	CX120
Belt - Straw Chopper; W/Std. Cut Bailing; W/174" Belt O.C. ....	H160654	C170
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH158880	C90
<b>2001-2000</b>		
Belt - Air Flow Fan Drive .....	H171386	B108
Belt - Alt.; W/185A. Alt. ....	H166870	▲K080878HD
Belt - Alt.; W/95A. Alt. ....	H163515	▲K080872HD
Belt - Beater Drive; W/100 Percent Beater Speed .....	AH139436	②C73
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Chopper; W/Fine Cut Bailing; W/123" Belt O.C. ....	H22529	B120
Belt - Straw Chopper; W/Std. Cut Bailing; W/124" Belt O.C. ....	H23950	CX120
Belt - Straw Chopper; W/Std. Cut Bailing; W/174" Belt O.C. ....	H160654	C170
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH158880	C90
<b>1999</b>		
Belt - Air Flow Fan Drive .....	H171386	B108
Belt - Alt.; W/185A. Alt. ....	H166870	▲K080878HD
Belt - Alt.; W/95A. Alt. ....	H163515	▲K080872HD
Belt - Beater Drive .....	AH139436	②C73
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Chopper; W/Fine Cut Bailing; W/123" Belt O.C. ....	H22529	B120
Belt - Straw Chopper; W/Std. Cut .....	H160654	C170
Belt - Straw Chopper; W/Std. Cut Bailing; W/124" Belt O.C. ....	H23950	CX120
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH158880	C90
<b>9650 CTS</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
<b>2003-2002</b>		
Belt - Alt.; W/185A. Alt. ....	R164820	▲K080468HD
Belt - Alt.; W/95A. Alt. ....	H163515	▲K080872HD
Belt - Cooling Fan .....	H177186	▲K080910HD
Belt - Overshot Beater Drive .....	H139963	B54
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Spreader - Lower .....	P49604	B92
Belt - Straw Spreader - Upper .....	H164870	B54
Belt - Stripper Beater Drive .....	H165708	2/B80
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH158880	②C90

②Two Required ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9650 CTS – Continued</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel – Continued</b>		
<b>2001–2000</b>		
Belt - Alt.; W/185A. Alt. ....	H166870	▲K080878HD
Belt - Alt.; W/95A. Alt. ....	H163515	▲K080872HD
Belt - Overshot Beater Drive .....	H139963	B54
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Spreader - Lower .....	P49604	B92
Belt - Straw Spreader - Upper .....	H164870	B54
Belt - Stripper Beater Drive .....	H165708	2/B80
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH158880	②C90
<b>1999</b>		
Belt - Air Flow Fan Drive .....	H171386	B108
Belt - Alt.; W/185A. Alt. ....	H166870	▲K080878HD
Belt - Alt.; W/95A. Alt. ....	H163515	▲K080872HD
Belt - Overshot Beater Drive .....	H139963	B54
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Spreader - Lower .....	P49604	B92
Belt - Straw Spreader - Upper .....	H164870	B54
Belt - Stripper Beater Drive .....	H165708	2/B80
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH158880	②C90
<b>9650 STS</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
<b>2003–2002</b>		
Belt - Serpentine - Alt.; W/185A. Alt. ....	R135609	▲K080790HD
Belt - Alt.; W/95A. Alt. ....	R135606	▲K080774HD
Belt - Discharge Beater .....	H168301	C130
Belt - Feeder House; W/Fixed Speed Drive; Ser. No. 700500 & Before .....	H111519	D158
<b>2001–1999</b>		
Belt - Serpentine - Alt.; W/185A. Alt. ....	R135609	▲K080790HD
Belt - Alt.; W/95A. Alt. ....	R135606	▲K080774HD
Belt - Discharge Beater .....	H168301	C130
Belt - Feeder House; W/Fixed Speed Drive; Ser. No. 700500 & Before .....	H111519	D158
Belt - Rotary Screen Drive - Eng. Side .....	H157104	A79
<b>9660 CTS</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
<b>2005–2003</b>		
Belt - Serpentine - Alt.; W/185A. Alt. ....	R164820	▲K080468HD
Belt - Serpentine - Alt.; W/95A. Alt. ....	H163515	▲K080872HD
Belt - Serpentine - Fan .....	H177186	▲K080910HD
Belt - Air Flow Fan Drive .....	H171386	B108
Belt - Overshot Beater Drive .....	H139963	B54
Belt - Rotary Screen Drive - Eng. Side .....	H146636	XPA1000
Belt - Straw Spreader - Lower .....	P49604	B92
Belt - Straw Spreader - Upper .....	H164870	B54
Belt - Stripper Beater Drive .....	H165708	2/B80
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloader Drive .....	AH158880	C90
<b>9660 STS</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
<b>2007–2003</b>		
Belt - Serpentine - Alt.; W/185A. Alt. ....	R135609	▲K080790HD
Belt - Serpentine - Alt.; W/200A. Alt. ....	AT262958	▲K080934HD
Belt - Serpentine - Alt.; W/95A. Alt. ....	R135606	▲K080774HD
Belt - Discharge Beater .....	H168301	C130
Belt - J.S. - Front (Right Hand); W/Edible Bean .....	AC144	C144
Belt - Tailings Auger & Elevator; W/Edible Bean .....	AC72	C72
<b>9670 STS</b>		
<b>John Deere 6–Cyl. 9.0 L Diesel</b>		
<b>2009</b>		
Belt - Serpentine .....	AT262958	▲K080934HD
Belt - Alt. ....	AT262958	▲K080934HD
Belt - J.S. - Front (Right Hand); W/Edible Bean .....	AC144	C144
Belt - Tailings Auger & Elevator; W/Edible Bean .....	AC72	C72

②Two Required ▲Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9670 STS – Continued</b>		
<b>John Deere 6–Cyl. 9.0 L Diesel – Continued</b>		
<b>2009 – Continued</b>		
Tensioner Assy. - Serpentine .....	RE518097	38507
<b>2008</b>		
Belt - Serpentine - Alt. ....	AT262958	▲K080934HD
Belt - Discharge Beater .....	H168301	C130
Belt - J.S. - Front (Right Hand); W/Edible Bean .....	AC144	C144
Belt - Tailings Auger & Elevator; W/Edible Bean .....	AC72	C72
<b>9750 STS</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
<b>2003</b>		
Belt - Serpentine - Alt.; W/185A. Alt. ....	R135609	▲K080790HD
Belt - Alt.; W/95A. Alt. ....	R135606	▲K080774HD
Belt - Discharge Beater .....	H168301	C130
Belt - Feeder House; W/Fixed Speed Drive; Ser. No. 700600 & Before .....	H111519	D158
<b>2002–1999</b>		
Belt - Serpentine - Alt.; W/185A. Alt. ....	R135609	▲K080790HD
Belt - Alt.; W/95A. Alt. ....	R135606	▲K080774HD
Belt - Discharge Beater .....	H168301	C130
Belt - Feeder House; W/Fixed Speed Drive; Ser. No. 700600 & Before .....	H111519	D158
Belt - Rotary Screen Drive - Eng. Side .....	H157104	A79
<b>9760 STS</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
<b>2007–2003</b>		
Belt - Serpentine - Alt.; W/185A. Alt. ....	R135609	▲K080790HD
Belt - Serpentine - Alt.; W/200A. Alt. ....	AT262958	▲K080934HD
Belt - Serpentine - Alt.; W/95A. Alt. ....	R135606	▲K080774HD
Belt - Discharge Beater .....	H168301	C130
Belt - J.S. - Front (Right Hand); W/Edible Bean .....	AC144	C144
Belt - Tailings Auger & Elevator; W/Edible Bean .....	AC72	C72
<b>9770 STS</b>		
<b>John Deere 6–Cyl. 9.0 L Diesel</b>		
<b>2009</b>		
Belt - Serpentine .....	AT262958	▲K080934HD
Tensioner Assy. ....	RE518097	38507
<b>2008</b>		
Belt - Serpentine - Alt. ....	AT262958	▲K080934HD
Belt - Discharge Beater .....	H168301	C130
Belt - J.S. - Front (Right Hand); W/Edible Bean .....	AC144	C144
Belt - Tailings Auger & Elevator; W/Edible Bean .....	AC72	C72
<b>9860 STS</b>		
<b>John Deere 6–Cyl. 12.5 L Diesel</b>		
<b>2007</b>		
Belt - Serpentine .....	R503505	▲K080855HD
Belt - Discharge Beater .....	H168301	C130
Belt - J.S. - Front (Right Hand); W/Edible Bean .....	AC144	C144
Belt - Tailings Auger & Elevator; W/Edible Bean .....	AC72	C72
Tensioner Assy. - Fan .....	RE506352	38591
<b>2006</b>		
Belt - Serpentine; W/185A. Alt.; Ser. No. 715633 & Before .....	R503505	▲K080855HD
Belt - Serpentine; W/200A. Alt.; Ser. No. 715634 & After .....	R503505	▲K080855HD
Belt - Serpentine; W/95A. Alt.; Ser. No. 715633 & Before .....	R503505	▲K080855HD
Belt - Discharge Beater .....	H168301	C130
Belt - J.S. - Front (Right Hand); W/Edible Bean .....	AC144	C144
Belt - Tailings Auger & Elevator; W/Edible Bean .....	AC72	C72
Tensioner Assy. - Fan .....	RE506352	38591

Agricultural Equipment



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9860 STS – Continued</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel – Continued</b>		
2005-2003		
Belt - Serpentine; W/185A. Alt .....	R503505	▲K080855HD
Belt - Serpentine; W/95A. Alt .....	R503505	▲K080855HD
Belt - Discharge Beater .....	H168301	C130
Belt - J.S. - Front (Right Hand); W/Edible Bean .....	AC144	C144
Belt - Tailings Auger & Elevator; W/Edible Bean .....	AC72	C72
Tensioner Assy. - Fan .....	RE506352	38591
<b>9870 STS</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>		
2009-2008		
Belt - Serpentine - Alt.; W/200A. Alt .....	R503505	▲K080855HD
Belt - Discharge Beater .....	H168301	C130
Belt - Fan - From C.S. ....	R503312	▲K120720HD
Belt - J.S. - Rear (Right Hand); W/Edible Bean .....	AC144	C144
Belt - Tailings Auger & Elevator; W/Edible Bean .....	AC72	C72
Tensioner Assy. - Alt. ....	RE506352	38591
Tensioner Assy. - Fan .....	RE249801	38530
<b>CTS</b>		
<b>John Deere 6-Cyl. 7.6 L Diesel</b>		
1997-1992		
Belt - A.C.; W/53 3/8" Belt O.C.; Ser. No. 650400 & Before .....	H81742	▲9530HD
Belt - A.C.; W/56 3/8" Belt O.C.; Ser. No. 650401 & After .....	H80896	▲9560HD
Belt - A.C.; W/58 3/8" Belt O.C. ....	H134437	▲9580HD
Belt - Alt. ....	H101813	▲9580HD
Belt - Rotary Screen Drive Shaft; Ser. No. 645511 & After .....	H146636	XPA1000
Belt - Straw Chopper; W/Std. Cut Bailing .....	H168301	C130
Belt - Straw Spreader; W/53" Belt O.C. ....	E61326	B50
Belt - Straw Spreader; W/95" Belt O.C. ....	P49604	B92
Belt - Straw Spreader - Lower .....	P49604	B92
Belt - Straw Spreader - Upper .....	E61326	B50
Belt - Stripper Beater Drive .....	H139963	B54
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH158880	ⓄC90
<b>CTS II</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
1999-1997		
Belt - A.C. ....	H134437	▲9580HD
Belt - Alt. ....	H101813	▲9580HD
Belt - Rotary Screen Drive Shaft .....	H146636	XPA1000
Belt - Straw Chopper; W/Std. Cut Bailing .....	H168301	C130
Belt - Straw Spreader - Lower .....	P49604	B92
Belt - Straw Spreader - Upper .....	E61326	B50
Belt - Stripper Beater Drive .....	H139963	B54
Belt - Tailings - Lower Auger & Elevator .....	N110085	C128
Belt - Unloading System .....	AH158880	ⓄC90
<b>T670</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2009		
Belt - Serpentine .....	H174455	▲K080903HD

ⓄTwo Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>60SP – Continued</b>		
<b>Chrysler 6-Cyl. 225 – Continued</b>		
1959-1953 – Continued		
Belt - Hyd. Pump; Ser. No. 251094 & Before ..	210716M1	B57
Belt - Hyd. Pump; Ser. No. 251095 & After .....	210810M1	B51
Belt - W.P. & Gen. ....	1506373M1	TR24489
<b>72SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1965-1959		
Belt - Fan .....	213850M1	B90
Belt - Gov. ....	211740M2	TR22350
Belt - Hyd. Pump .....	210810M1	B51
Belt - W.P. & Gen. ....	1506373M1	TR24489
<b>80SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1956-1952		
Belt - Fan; Ser. No. 208479 & After .....	213850M1	B90
Belt - Gov. ....	211740M2	TR22350
Belt - Hyd. Pump; W/Bendix Pump .....	210716M1	B57
Belt - Hyd. Pump; W/Pesco Pump .....	210810M1	B51
Belt - W.P. & Gen. ....	1506373M1	TR24489
<b>82SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1963-1957		
Belt - Fan .....	213850M1	B90
Belt - Gov. ....	211740M1	TR22350
Belt - Hyd. Pump .....	210810M1	B51
Belt - W.P. & Gen. ....	213850M1	B90
<b>92SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1959-1957		
Belt - Fan; Ser. No. 157118 & Before .....	213850M1	B90
Belt - Fan; Ser. No. 157119 & After .....	220773M1	B94
Belt - Gov. ....	211740M2	TR22350
Belt - Hyd. Pump .....	210716M1	B57
Belt - W.P. & Gen. ....	1506373M1	TR24489
<b>205SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1971-1966		
Belt - Alt. ....	833668M1	7425
<b>Chrysler 6-Cyl. 225 Diesel</b>		
1971-1966		
Belt - Alt. ....	833668M1	7425
<b>300SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1977-1969		
Belt - Aux. Cyl. ....	832822M1	B105
Belt - Cleaner Fan - Lower .....	832876M1	B48
Belt - Cleaner Fan - Upper .....	832877M1	B56
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Gov. ....	235199M1	7450
Belt - Grass Seed - Right Hand .....	GH5047	B55
Belt - Hyd. Pump .....	230381M1	C53
Belt - Knife Wobble; W/88" Belt O.C. ....	834058M1	C84
Belt - Knife Wobble; W/89" Belt O.C. ....	834190M1	C85
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Rotary Screen Countershaft .....	832895M2	A35
Belt - Rotary Screen Hyd. Pump .....	834148M1	A38
Belt - Straw Walker .....	832867M1	B133
Belt - Table Drive .....	228147M91	ⓄB50
Belt - W.P. & Alt. ....	834063M1	7560
<b>1968</b>		
Belt - Aux. Cyl. ....	832822M1	B105
Belt - Cleaner Fan - Lower .....	832876M1	B48
Belt - Cleaner Fan - Upper .....	832877M1	B56
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Gov. ....	235199M1	7450
Belt - Grass Seed - Right Hand .....	GH5047	B55

Agricultural Equipment



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>300SP - Continued</b>		
<b>Chrysler 6-Cyl. 225 - Continued</b>		
<b>1968 - Continued</b>		
Belt - Hyd. Pump .....	230381M1	C53
Belt - Knife Wobble; W/88" Belt O.C. ....	834058M1	C84
Belt - Knife Wobble; W/89" Belt O.C. ....	834190M1	C85
Belt - Reel Drive; W/Fixed Speed Drive .....	227984M1	C144
Belt - Rotary Screen Countershaft .....	832895M2	A35
Belt - Rotary Screen Hyd. Pump .....	834148M1	A38
Belt - Straw Walker .....	832867M1	B133
Belt - Table Drive .....	228147M91	②B50
Belt - W.P. & Alt. ....	834063M1	7560
<b>1967-1966</b>		
Belt - Aux. Cyl. ....	832822M1	B105
Belt - Cleaner Fan - Lower .....	832876M1	B48
Belt - Cleaner Fan - Upper .....	832877M1	B56
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Gen. & W.P. ....	1023962M1	7425
Belt - Gov. ....	235199M1	7450
Belt - Grass Seed - Right Hand .....	GH5047	B55
Belt - Hyd. Pump .....	230381M1	C53
Belt - Rad. Fan .....	236670M1	▲9560HD
Belt - Reel Drive; W/Fixed Speed Drive .....	227984M1	C144
Belt - Rotary Screen Countershaft .....	832895M2	A35
Belt - Straw Walker .....	832867M1	B133
<b>1965-1962</b>		
Belt - Aux. Cyl. ....	832822M1	B105
Belt - Cleaner Fan - Lower .....	832876M1	B48
Belt - Cleaner Fan - Upper .....	832877M1	B56
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Gen. & W.P. ....	1023962M1	7425
Belt - Gov. ....	235199M1	7450
Belt - Grass Seed - Right Hand .....	GH5047	B55
Belt - Hyd. Pump .....	230381M1	C53
Belt - Rad. Fan .....	236670M1	▲9560HD
Belt - Reel Drive; W/Fixed Speed Drive .....	832872M1	C128
Belt - Rotary Screen Countershaft .....	832895M2	A35
Belt - Straw Walker .....	832867M1	B133
<b>Chrysler 6-Cyl. 225 Diesel</b>		
<b>1977-1969</b>		
Belt - Aux. Cyl. ....	832822M1	B105
Belt - Cleaner Fan - Lower .....	832876M1	B48
Belt - Cleaner Fan - Upper .....	832877M1	B56
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grass Seed - Right Hand .....	GH5047	B55
Belt - Hyd. Pump .....	230381M1	C53
Belt - Knife Wobble; W/88" Belt O.C. ....	834058M1	C84
Belt - Knife Wobble; W/89" Belt O.C. ....	834190M1	C85
Belt - Rad. Fan .....	236958M1	▲9550HD
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Rotary Screen Countershaft .....	832896M1	A60
Belt - Straw Walker .....	832867M1	B133
Belt - Table Drive .....	228147M91	②B50
Belt - W.P. & Alt. ....	834060M1	7480
Hose - Upper .....		●26508
Hose - Lower .....		24224
<b>1968</b>		
Belt - Aux. Cyl. ....	832822M1	B105
Belt - Cleaner Fan - Lower .....	832876M1	B48
Belt - Cleaner Fan - Upper .....	832877M1	B56
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grass Seed - Right Hand .....	GH5047	B55
Belt - Hyd. Pump .....	230381M1	C53
Belt - Knife Wobble; W/88" Belt O.C. ....	834058M1	C84
Belt - Knife Wobble; W/89" Belt O.C. ....	834190M1	C85
Belt - Rad. Fan .....	236958M1	▲9550HD
Belt - Reel Drive; W/Fixed Speed Drive .....	227984M1	C144
Belt - Rotary Screen Countershaft .....	832896M1	A60
Belt - Straw Walker .....	832867M1	B133
Belt - Table Drive .....	228147M91	②B50
Belt - W.P. & Alt. ....	834060M1	7480
Hose - Upper .....		●26508
Hose - Lower .....		24224
<b>1967-1966</b>		
Belt - Aux. Cyl. ....	832822M1	B105
Belt - Cleaner Fan - Lower .....	832876M1	B48
Belt - Cleaner Fan - Upper .....	832877M1	B56

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>300SP - Continued</b>		
<b>Chrysler 6-Cyl. 225 Diesel - Continued</b>		
<b>1967-1966 - Continued</b>		
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Gen. & W.P. ....	236959M1	▲9490HD
Belt - Grass Seed - Right Hand .....	GH5047	B55
Belt - Hyd. Pump .....	230381M1	C53
Belt - Rad. Fan .....	236958M1	▲9550HD
Belt - Reel Drive; W/Fixed Speed Drive .....	227984M1	C144
Belt - Rotary Screen Countershaft .....	832896M1	A60
Belt - Straw Walker .....	832867M1	B133
Hose - Upper .....		●26508
Hose - Lower .....		24224
<b>1965-1962</b>		
Belt - Aux. Cyl. ....	832822M1	B105
Belt - Cleaner Fan - Lower .....	832876M1	B48
Belt - Cleaner Fan - Upper .....	832877M1	B56
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Gen. & W.P. ....	236959M1	▲9490HD
Belt - Grass Seed - Right Hand .....	GH5047	B55
Belt - Hyd. Pump .....	230381M1	C53
Belt - Rad. Fan .....	236958M1	▲9550HD
Belt - Reel Drive; W/Fixed Speed Drive .....	832872M1	C128
Belt - Rotary Screen Countershaft .....	832896M1	A60
Belt - Straw Walker .....	832867M1	B133
Hose - Upper .....		●26508
Hose - Lower .....		24224
<b>410SP</b>		
<b>Chevrolet 6-Cyl. 292</b>		
<b>1972-1969</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	834139M1	C71
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	230380M1	TR28583
Belt - Knife Wobble .....	834058M1	C84
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	834140M1	C144
Belt - Rotary Screen .....	228722M1	B50
Belt - Slinger .....	834332M1	B95
Belt - Straw Chopper .....	1033199M1	C345
Belt - Straw Spreader; W/Single Spreader .....	833563M1	B173
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P. & Alt. ....	834060M1	7480
Belt - W.P. & Gen. ....	238859M1	▲9415HD
<b>1968</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	834139M1	C71
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	230380M1	TR28583
Belt - Knife Wobble .....	834058M1	C84
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	834140M1	C144
Belt - Rotary Screen .....	228722M1	B50
Belt - Slinger; Exc. Field Installed Kit .....	833742M1	B98
Belt - Slinger; For Field Installed Kit .....	834332M1	B95
Belt - Straw Chopper .....	1033199M1	C345
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	B133
Belt - Straw Spreader; W/Single Spreader .....	833563M1	B173
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P. & Alt. ....	834060M1	7480
Belt - W.P. & Gen. ....	238859M1	▲9415HD
<b>1967</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	227457M1	C73
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	230380M1	TR28583
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	227455M1	C126
Belt - Rotary Screen .....	228722M1	B50
Belt - Slinger; Exc. Field Installed Kit .....	833742M1	B98

②Two Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>410SP - Continued</b>		
<b>Chevrolet 6-Cyl. 292 - Continued</b>		
<b>1967 - Continued</b>		
Belt - Slinger; For Field Installed Kit .....	222347M1	B81
Belt - Straw Chopper .....	1033199M1	C345
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	B133
Belt - Straw Spreader; W/Single Spreader .....	833563M1	B173
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P. & Alt. ....	834060M1	7480
Belt - W.P. & Gen. ....	238859M1	▲9415HD
<b>1966</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	227457M1	C73
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	230380M1	TR28583
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	227455M1	C126
Belt - Rotary Screen .....	228722M1	B50
Belt - Slinger; Exc. Field Installed Kit .....	228999M1	B72
Belt - Slinger; For Field Installed Kit .....	222347M1	B81
Belt - Straw Chopper .....	1033137M1	C330
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	B133
Belt - Straw Spreader; W/Single Spreader .....	833563M1	B173
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P. & Alt. ....	834060M1	7480
Belt - W.P. & Gen. ....	238859M1	▲9415HD
<b>1965</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	227457M1	C73
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	230380M1	TR28583
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	227455M1	C126
Belt - Rotary Screen .....	228722M1	B50
Belt - Slinger; Exc. Field Installed Kit .....	228999M1	B72
Belt - Slinger; For Field Installed Kit .....	222347M1	B81
Belt - Straw Chopper .....	1033137M1	C330
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	B133
Belt - Straw Spreader; W/Single Spreader .....	833563M1	B173
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P. & Alt.; Ser. No. 6777 & After .....	834060M1	7480
Belt - W.P. & Gen. ....	238859M1	▲9415HD
<b>1964</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	227457M1	C73
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	230380M1	TR28583
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	227455M1	C126
Belt - Rotary Screen .....	228722M1	B50
Belt - Slinger; Exc. Field Installed Kit .....	228999M1	B72
Belt - Slinger; For Field Installed Kit .....	222347M1	B81
Belt - Straw Chopper .....	1033137M1	C330
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	B133
Belt - Straw Spreader; W/Single Spreader .....	833563M1	B173
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P. & Gen. ....	238859M1	▲9415HD
<b>Perkins 4-Cyl. 318 Diesel</b>		
<b>1972-1969</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	834139M1	C71
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	832490M1	5VX530
Belt - Knife Wobble .....	834058M1	C84
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	834140M1	C144
Belt - Rotary Screen .....	228722M1	B50
Belt - Straw Chopper .....	1033199M1	C345
Belt - Tank Unloader .....	228813M3	C57

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>410SP - Continued</b>		
<b>Perkins 4-Cyl. 318 Diesel - Continued</b>		
<b>1972-1969 - Continued</b>		
Belt - W.P. & Alt. ....	252164M1	7512
Belt - W.P. & Gen. ....	230350M1	▲9505HD
<b>1968</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	834139M1	C71
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	832490M1	5VX530
Belt - Knife Wobble .....	834058M1	C84
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	834140M1	C144
Belt - Rotary Screen .....	228722M1	B50
Belt - Straw Chopper .....	1033199M1	C345
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	B133
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P. & Alt. ....	252164M1	7512
Belt - W.P. & Gen. ....	230350M1	▲9505HD
<b>1967</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	227457M1	C73
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	832490M1	5VX530
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	227455M1	C126
Belt - Rotary Screen .....	228722M1	B50
Belt - Straw Chopper .....	1033199M1	C345
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	B133
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P. & Alt. ....	252164M1	7512
Belt - W.P. & Gen. ....	230350M1	▲9505HD
<b>1966</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	227457M1	C73
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	832490M1	5VX530
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	227455M1	C126
Belt - Rotary Screen .....	228722M1	B50
Belt - Straw Chopper .....	1033137M1	C330
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	B133
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P. & Alt. ....	252164M1	7512
Belt - W.P. & Gen. ....	230350M1	▲9505HD
<b>1965</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	227457M1	C73
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	832490M1	5VX530
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	227455M1	C126
Belt - Rotary Screen .....	228722M1	B50
Belt - Straw Chopper .....	1033137M1	C330
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	B133
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P. & Alt.; Ser. No. 6777 & After .....	252164M1	7512
Belt - W.P. & Gen. ....	230350M1	▲9505HD
<b>1964</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel; Grain .....	227457M1	C73
Belt - Gov. ....	238891M1	7555
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	832490M1	5VX530
Belt - Rad. Fan .....	240575M2	B48
Belt - Reel Drive; Grain .....	227455M1	C126
Belt - Rotary Screen .....	228722M1	B50
Belt - Straw Chopper .....	1033137M1	C330

▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>410SP - Continued</b>		
<b>Perkins 4-Cyl. 318 Diesel - Continued</b>		
<b>1964 - Continued</b>		
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	<b>B133</b>
Belt - Tank Unloader .....	228813M3	<b>C57</b>
Belt - W.P. & Gen. ....	230350M1	<b>▲9505HD</b>
<b>510SP</b>		
<b>Chevrolet V-8 350</b>		
<b>1978</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	<b>B54</b>
Belt - Cleaner Fan & Countershaft .....	227457M1	<b>C73</b>
Belt - Countershaft - Reel; Grain .....	834139M1	<b>C71</b>
Belt - Gov. ....	234995M1	<b>7520</b>
Belt - Grain Auger .....	227984M1	<b>C144</b>
Belt - Hyd. Pump .....	230380M1	<b>TR28583</b>
Belt - Knife Wobble; Ser. No. 12019077 Thru 185937751; W/13 Ft. Chain .....	834058M1	<b>C84</b>
Belt - Knife Wobble; Ser. No. 185937752 & After .....	834190M1	<b>C85</b>
Belt - Pickup Drive; W/67" Drive .....	1047702M1	<b>B122</b>
Belt - Rad. Fan .....	240575M2	<b>B48</b>
Belt - Reel Drive; Grain .....	834140M1	<b>C144</b>
Belt - Rotary Screen .....	228722M1	<b>B50</b>
Belt - Slinger .....	834332M1	<b>B95</b>
Belt - Straw Spreader; W/Single Spreader .....	833131M1	<b>A180</b>
Belt - Tank Unloader .....	228813M3	<b>C57</b>
Belt - W.P. & Alt.; Ser. No. 9077 & Before; W/Hydro. Drive .....	252164M1	<b>7512</b>
Belt - W.P. & Alt.; Ser. No. 9077 & Before; W/O Hydro. Drive .....	240807M1	<b>▲9540HD</b>
Belt - W.P. & Gen. ....	240807M1	<b>▲9540HD</b>
Hose - Upper .....		<b>●26505</b>
Hose - Lower .....		<b>24224</b>
<b>1977-1975</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	<b>B54</b>
Belt - Cleaner Fan & Countershaft .....	227457M1	<b>C73</b>
Belt - Countershaft - Reel; Grain .....	834139M1	<b>C71</b>
Belt - Gov. ....	234995M1	<b>7520</b>
Belt - Grain Auger .....	227984M1	<b>C144</b>
Belt - Hyd. Pump .....	230380M1	<b>TR28583</b>
Belt - Knife Wobble; Ser. No. 12019077 Thru 185937751 .....	834058M1	<b>C84</b>
Belt - Knife Wobble; Ser. No. 185937752 & After .....	834190M1	<b>C85</b>
Belt - Pickup Drive; W/67" Drive .....	1047702M1	<b>B122</b>
Belt - Rad. Fan .....	240575M2	<b>B48</b>
Belt - Reel Drive; Grain .....	834140M1	<b>C144</b>
Belt - Rotary Screen .....	228722M1	<b>B50</b>
Belt - Slinger .....	834332M1	<b>B95</b>
Belt - Straw Spreader; W/Single Spreader .....	833131M1	<b>A180</b>
Belt - Tank Unloader .....	228813M3	<b>C57</b>
Belt - W.P. & Alt.; Ser. No. 9077 & Before; W/Hydro. Drive .....	252164M1	<b>7512</b>
Belt - W.P. & Alt.; Ser. No. 9077 & Before; W/O Hydro. Drive .....	240807M1	<b>▲9540HD</b>
Belt - W.P. & Gen. ....	240807M1	<b>▲9540HD</b>
Hose - Upper .....		<b>●26505</b>
Hose - Lower .....		<b>24224</b>
<b>Perkins 6-Cyl. 354 Diesel</b>		
<b>1978-1975</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	<b>B54</b>
Belt - Cleaner Fan & Countershaft .....	227457M1	<b>C73</b>
Belt - Countershaft - Reel; Grain .....	834139M1	<b>C71</b>
Belt - Grain Auger .....	227984M1	<b>C144</b>
Belt - Hyd. Pump .....	230381M1	<b>C53</b>
Belt - Knife Wobble; Ser. No. 12019077 Thru 185937751 .....	834058M1	<b>C84</b>
Belt - Knife Wobble; Ser. No. 185937752 & After .....	834190M1	<b>C85</b>
Belt - Pickup Drive; W/67" Drive .....	1047702M1	<b>B122</b>
Belt - Rad. Fan .....	240575M2	<b>B48</b>
Belt - Reel Drive; Grain .....	834140M1	<b>C144</b>
Belt - Rotary Screen .....	228722M1	<b>B50</b>
Belt - Slinger .....	834332M1	<b>B95</b>
Belt - Straw Spreader; W/Single Spreader .....	833131M1	<b>A180</b>
Belt - Tank Unloader .....	228813M3	<b>C57</b>
Belt - W.P. & Alt. ....	834061M1	<b>7495</b>

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>510SP - Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel - Continued</b>		
<b>1978-1975 - Continued</b>		
Belt - W.P. & Gen.; Ser. No. 9077 & Before ...	230350M1	<b>▲9505HD</b>
Hose - Upper .....		<b>▼20685</b>
Hose - Lower .....		<b>▼20065</b>
<b>1974-1969</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	<b>B54</b>
Belt - Cleaner Fan & Countershaft .....	227457M1	<b>C73</b>
Belt - Countershaft - Reel; Grain .....	834139M1	<b>C71</b>
Belt - Grain Auger .....	227984M1	<b>C144</b>
Belt - Hyd. Pump .....	230381M1	<b>C53</b>
Belt - Knife Wobble; Ser. No. 12019077 Thru 185937751 .....	834058M1	<b>C84</b>
Belt - Knife Wobble; Ser. No. 185937752 & After .....	834190M1	<b>C85</b>
Belt - Pickup Drive; W/67" Drive .....	1047702M1	<b>B122</b>
Belt - Rad. Fan .....	240575M2	<b>B48</b>
Belt - Reel Drive; Grain .....	834140M1	<b>C144</b>
Belt - Rotary Screen .....	228722M1	<b>B50</b>
Belt - Slinger .....	834332M1	<b>B95</b>
Belt - Straw Spreader; W/Single Spreader .....	833131M1	<b>A180</b>
Belt - Tank Unloader .....	228813M3	<b>C57</b>
Belt - W.P. & Alt. ....	834061M1	<b>7495</b>
Belt - W.P. & Gen.; Ser. No. 9077 & Before ...	230350M1	<b>▲9505HD</b>
<b>1968</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	<b>B54</b>
Belt - Cleaner Fan & Countershaft .....	227457M1	<b>C73</b>
Belt - Countershaft - Reel; Grain .....	834139M1	<b>C71</b>
Belt - Grain Auger .....	227984M1	<b>C144</b>
Belt - Hyd. Pump .....	230381M1	<b>C53</b>
Belt - Knife Wobble; Ser. No. 12019077 Thru 185937751 .....	834058M1	<b>C84</b>
Belt - Knife Wobble; Ser. No. 185937752 & After .....	834190M1	<b>C85</b>
Belt - Pickup Drive; W/67" Drive .....	1047702M1	<b>B122</b>
Belt - Rad. Fan .....	240575M2	<b>B48</b>
Belt - Reel Drive; Grain .....	834140M1	<b>C144</b>
Belt - Rotary Screen .....	228722M1	<b>B50</b>
Belt - Slinger .....	833742M1	<b>B98</b>
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	<b>B133</b>
Belt - Straw Spreader; W/Single Spreader .....	833131M1	<b>A180</b>
Belt - Tank Unloader .....	228813M3	<b>C57</b>
Belt - W.P. & Alt. ....	834061M1	<b>7495</b>
Belt - W.P. & Gen.; Ser. No. 9077 & Before ...	230350M1	<b>▲9505HD</b>
<b>1967</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	<b>B54</b>
Belt - Cleaner Fan & Countershaft .....	227457M1	<b>C73</b>
Belt - Countershaft - Reel; Grain .....	227457M1	<b>C73</b>
Belt - Grain Auger .....	227984M1	<b>C144</b>
Belt - Hyd. Pump .....	230381M1	<b>C53</b>
Belt - Knife Wobble; Ser. No. 12019077 Thru 185937751 .....	834058M1	<b>C84</b>
Belt - Knife Wobble; Ser. No. 185937752 & After .....	834190M1	<b>C85</b>
Belt - Pickup Drive; W/67" Drive .....	1047702M1	<b>B122</b>
Belt - Rad. Fan .....	240575M2	<b>B48</b>
Belt - Reel Drive; Grain .....	227455M1	<b>C126</b>
Belt - Rotary Screen .....	228722M1	<b>B50</b>
Belt - Slinger .....	833742M1	<b>B98</b>
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	<b>B133</b>
Belt - Straw Spreader; W/Single Spreader .....	833131M1	<b>A180</b>
Belt - Tank Unloader .....	228813M3	<b>C57</b>
Belt - W.P. & Alt. ....	834061M1	<b>7495</b>
Belt - W.P. & Gen.; Ser. No. 9077 & Before ...	230350M1	<b>▲9505HD</b>
<b>1966-1964</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	<b>B54</b>
Belt - Cleaner Fan & Countershaft .....	227457M1	<b>C73</b>
Belt - Countershaft - Reel; Grain .....	227457M1	<b>C73</b>
Belt - Grain Auger .....	227984M1	<b>C144</b>
Belt - Hyd. Pump .....	230381M1	<b>C53</b>
Belt - Knife Wobble; Ser. No. 12019077 Thru 185937751 .....	834058M1	<b>C84</b>
Belt - Knife Wobble; Ser. No. 185937752 & After .....	834190M1	<b>C85</b>
Belt - Pickup Drive; W/67" Drive .....	1047702M1	<b>B122</b>
Belt - Rad. Fan .....	240575M2	<b>B48</b>
Belt - Reel Drive; Grain .....	227455M1	<b>C126</b>

◀Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>510SP - Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel - Continued</b>		
<b>1966-1964 - Continued</b>		
Belt - Rotary Screen .....	228722M1	B50
Belt - Slinger; Exc. Field Installed Kit .....	228999M1	B72
Belt - Slinger; For Field Installed Kit .....	222347M1	B81
Belt - Straw Chopper .....	1033137M1	C330
Belt - Straw Spreader; W/Dual Spreader .....	832446M1	B133
Belt - Straw Spreader; W/Single Spreader .....	833131M1	A180
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P. & Alt. ....	834061M1	7495
Belt - W.P. & Gen.; Ser. No. 9077 & Before ...	230350M1	▲9505HD
<b>540SP</b>		
<b>Perkins 4-Cyl. 318 Diesel</b>		
<b>1985-1980</b>		
Belt - A.C. ....	843045M1	▲9451HD
Belt - Air Intake .....	240575M2	B48
Belt - Cleaner Fan .....	832877M1	B56
Belt - Cleaner Fan & Countershaft .....	228997M1	B47
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Hyd. Pump .....	230380M1	TR28583
Belt - Knife Wobble; W/Speed Up 15, 16, 18, 20 ft. ....	843029M1	C90
Belt - Knife Wobble - Float Cutter Bar .....	833962M1	C115
Belt - Knife Wobble - Rigid Cutter Bar .....	834190M1	C85
Belt - Pickup Drive .....	1047702M1	B122
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Slinger .....	834332M1	B95
Belt - Straw Spreader .....	843742M1	B168
Belt - Straw Walker .....	832867M1	B133
Belt - W.P., Fan & Alt. ....	844171M1	7520
<b>1979-1978</b>		
Belt - A.C. ....	843045M1	▲9451HD
Belt - Air Intake .....	240575M2	B48
Belt - Cleaner Fan .....	832877M1	B56
Belt - Cleaner Fan & Countershaft .....	228997M1	B47
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Hyd. Pump .....	230380M1	TR28583
Belt - Knife Wobble; W/Speed Up 15, 16, 18, 20 ft. ....	843029M1	C90
Belt - Knife Wobble - Float Cutter Bar .....	833962M1	C115
Belt - Knife Wobble - Rigid Cutter Bar .....	834190M1	C85
Belt - Pickup Drive .....	1047702M1	B122
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Slinger .....	834332M1	B95
Belt - Straw Spreader .....	843742M1	B168
Belt - Straw Walker .....	832867M1	B133
Belt - W.P., Fan & Alt. ....	532779M92	②7516
<b>550</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
<b>1990</b>		
Belt - Chopper; W/Low Speed Corn Kit .....	842935M1	C51
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	843737M1	6955
Belt - Hydro. Drive - Lower .....	834176M1	B74
Belt - Knife Wobble - Centered Chain Drive ...	834058M1	C84
Belt - Knife Wobble - Float Cutter Bar .....	833962M1	C115
Belt - Knife Wobble - Rigid Cutter Bar; W/Std. Speed .....	834190M1	C85
Belt - Pickup Drive .....	1047702M1	B122
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Slinger .....	834332M1	B95
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P., Fan & Alt. ....	268847M91	②▲9520HD
Hose - Upper .....		②21379
		or ②●26509
Hose - Lower - Eng. To Pipe .....		●26515
Hose - Lower - Pipe To Rad. ....		24232
Hose - By Pass .....		≧20661
		or ●25251
<b>1989-1982</b>		
Belt - Chopper; W/Low Speed Corn Kit .....	842935M1	C51

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>550 - Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel - Continued</b>		
<b>1989-1982 - Continued</b>		
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	843737M1	6955
Belt - Hydro. Drive - Lower .....	834176M1	B74
Belt - Knife Wobble - Centered Chain Drive ...	834058M1	C84
Belt - Knife Wobble - Float Cutter Bar .....	833962M1	C115
Belt - Knife Wobble - Rigid Cutter Bar .....	834190M1	C85
Belt - Pickup Drive .....	1047702M1	B122
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Slinger .....	834332M1	B95
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P., Fan & Alt. ....	268847M91	②▲9520HD
Hose - Upper .....		②21379
		or ②●26509
Hose - Lower - Eng. To Pipe .....		●26515
Hose - Lower - Pipe To Rad. ....		24232
Hose - By Pass .....		≧20661
		or ●25251
<b>1981-1978</b>		
Belt - Chopper; W/Low Speed Corn Kit .....	842935M1	C51
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	843737M1	6955
Belt - Hydro. Drive - Lower .....	834176M1	B74
Belt - Knife Wobble - Centered Chain Drive ...	834058M1	C84
Belt - Knife Wobble - Float Cutter Bar .....	833962M1	C115
Belt - Knife Wobble - Rigid Cutter Bar .....	834190M1	C85
Belt - Pickup Drive .....	1047702M1	B122
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Slinger .....	834332M1	B95
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P., Fan & Alt. ....	532779M92	②7516
Hose - Upper .....		②21379
		or ②●26509
Hose - Lower - Eng. To Pipe .....		●26515
Hose - Lower - Pipe To Rad. ....		24232
Hose - By Pass .....		≧20661
		or ●25251
<b>550SP</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
<b>1990</b>		
Belt - Chopper; W/Low Speed Corn Kit .....	842935M1	C51
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	843737M1	6955
Belt - Hydro. Drive - Lower .....	834176M1	B74
Belt - Knife Wobble - Centered Chain Drive ...	834058M1	C84
Belt - Knife Wobble - Float Cutter Bar .....	833962M1	C115
Belt - Knife Wobble - Rigid Cutter Bar; W/Std. Speed .....	834190M1	C85
Belt - Pickup Drive .....	1047702M1	B122
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Slinger .....	834332M1	B95
Belt - Tank Unloader .....	228813M3	C57
Belt - W.P., Fan & Alt. ....	268847M91	②▲9520HD
<b>1989-1982</b>		
Belt - Chopper; W/Low Speed Corn Kit .....	842935M1	C51
Belt - Cleaner Fan - Std. Speed .....	227976M1	B54
Belt - Cleaner Fan & Countershaft .....	227457M1	C73
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Auger .....	227984M1	C144
Belt - Hyd. Pump .....	843737M1	6955
Belt - Hydro. Drive - Lower .....	834176M1	B74
Belt - Knife Wobble - Centered Chain Drive ...	834058M1	C84
Belt - Knife Wobble - Float Cutter Bar .....	833962M1	C115
Belt - Knife Wobble - Rigid Cutter Bar .....	834190M1	C85
Belt - Pickup Drive .....	1047702M1	B122
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>550SP - Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel - Continued</b>		
<b>1989-1982 - Continued</b>		
Belt - Slinger .....	834332M1	<b>B95</b>
Belt - Tank Unloader .....	228813M3	<b>C57</b>
Belt - W.P., Fan & Alt. ....	268847M91	② <b>▲9520HD</b>
<b>1981-1978</b>		
Belt - Chopper; W/Low Speed Corn Kit .....	842935M1	<b>C51</b>
Belt - Cleaner Fan - Std. Speed .....	227976M1	<b>B54</b>
Belt - Cleaner Fan & Countershaft .....	227457M1	<b>C73</b>
Belt - Countershaft - Reel .....	834139M1	<b>C71</b>
Belt - Grain Auger .....	227984M1	<b>C144</b>
Belt - Hyd. Pump .....	843737M1	<b>6955</b>
Belt - Hydro. Drive - Lower .....	834176M1	<b>B74</b>
Belt - Knife Wobble - Centered Chain Drive ...	834058M1	<b>C84</b>
Belt - Knife Wobble - Float Cutter Bar .....	833962M1	<b>C115</b>
Belt - Knife Wobble - Rigid Cutter Bar .....	834190M1	<b>C85</b>
Belt - Pickup Drive .....	1047702M1	<b>B122</b>
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	<b>C144</b>
Belt - Slinger .....	834332M1	<b>B95</b>
Belt - Tank Unloader .....	228813M3	<b>C57</b>
Belt - W.P., Fan & Alt. ....	532779M92	② <b>7516</b>
<b>750SP</b>		
<b>Chevrolet V-8 350</b>		
<b>1984-1979</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲ <b>9430HD</b>
Belt - Alt. ....	258627M91	② <b>7565</b>
Belt - Countershaft - Reel .....	834139M1	<b>C71</b>
Belt - Gov. ....	521398M91	<b>7585</b>
Belt - Grain Tank Unloader .....	833873M1	<b>2/B75</b>
Belt - Hyd. Pump; Ser. No. 169605386 & Before .....	222882M2	<b>B60</b>
Belt - Hyd. Pump; Ser. No. 169605387 & After .....	842413M2	<b>B56</b>
Belt - Hydro. Reel Pump .....	842845M1	<b>B78</b>
Belt - Rad. Fan .....	274339M91	② <b>A66</b>
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	<b>C144</b>
Belt - Return Elevator Drive .....	833854M2	<b>B116</b>
Belt - Shaker Shoe .....	273757M91	② <b>B154</b>
Belt - Shaker Shoe Countershaft Fan .....	281560M91	② <b>B90</b>
Belt - Straw Chopper - Rear .....	832906M1	<b>C158</b>
Belt - Straw Chopper Corn Kit .....	842935M1	<b>C51</b>
Belt - Straw Spreader .....	842110M1	<b>B192</b>
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	<b>C85</b>
<b>1978</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	843045M1	▲ <b>9451HD</b>
Belt - Alt. ....	258627M91	② <b>7565</b>
Belt - Countershaft - Reel .....	834139M1	<b>C71</b>
Belt - Gov. ....	521398M91	<b>7585</b>
Belt - Grain Tank Unloader .....	833873M1	<b>2/B75</b>
Belt - Hyd. Pump; Ser. No. 169605386 & Before .....	222882M2	<b>B60</b>
Belt - Hyd. Pump; Ser. No. 169605387 & After .....	842413M2	<b>B56</b>
Belt - Hydro. Reel Pump .....	842845M1	<b>B78</b>
Belt - Rad. Fan .....	274339M91	② <b>A66</b>
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	<b>C144</b>
Belt - Return Elevator Drive .....	833854M2	<b>B116</b>
Belt - Shaker Shoe .....	273757M91	② <b>B154</b>
Belt - Shaker Shoe Countershaft Fan; Ser. No. 15715 & Before .....	274015M91	② <b>B89</b>
Belt - Shaker Shoe Countershaft Fan; Ser. No. 15716 & After .....	281560M91	② <b>B90</b>
Belt - Straw Chopper Corn Kit .....	842935M1	<b>C51</b>
Belt - Straw Spreader .....	842110M1	<b>B192</b>
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	<b>C85</b>
<b>1977</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	843045M1	▲ <b>9451HD</b>
Belt - Air Intake .....	216897M1	<b>A70</b>
Belt - Alt. ....	258627M91	② <b>7565</b>
Belt - Countershaft - Reel .....	834139M1	<b>C71</b>
Belt - Gov. ....	521398M91	<b>7585</b>
Belt - Grain Tank Unloader .....	833873M1	<b>2/B75</b>
Belt - Hyd. Pump; Ser. No. 169605386 & Before .....	222882M2	<b>B60</b>
Belt - Hyd. Pump; Ser. No. 169605387 & After .....	842413M2	<b>B56</b>

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>750SP - Continued</b>		
<b>Chevrolet V-8 350 - Continued</b>		
<b>1977 - Continued</b>		
Belt - Hydro. Reel Pump .....	842845M1	<b>B78</b>
Belt - Rad. Fan .....	274339M91	② <b>A66</b>
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	<b>C144</b>
Belt - Return Elevator Drive .....	833854M2	<b>B116</b>
Belt - Shaker Shoe .....	273757M91	② <b>B154</b>
Belt - Shaker Shoe Countershaft Fan .....	274015M91	② <b>B89</b>
Belt - Straw Chopper Corn Kit .....	842935M1	<b>C51</b>
Belt - Straw Spreader .....	842110M1	<b>B192</b>
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	<b>C85</b>
<b>1976-1973</b>		
Belt - Air Intake .....	216897M1	<b>A70</b>
Belt - Alt. ....	258627M91	② <b>7565</b>
Belt - Countershaft - Reel .....	834139M1	<b>C71</b>
Belt - Gov. ....	521398M91	<b>7585</b>
Belt - Grain Tank Unloader .....	833873M1	<b>2/B75</b>
Belt - Hyd. Pump; Ser. No. 169605386 & Before .....	222882M2	<b>B60</b>
Belt - Hyd. Pump; Ser. No. 169605387 & After .....	842413M2	<b>B56</b>
Belt - Hydro. Reel Pump .....	842845M1	<b>B78</b>
Belt - Rad. Fan .....	274339M91	② <b>A66</b>
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	<b>C144</b>
Belt - Return Elevator Drive .....	833854M2	<b>B116</b>
Belt - Shaker Shoe .....	273757M91	② <b>B154</b>
Belt - Shaker Shoe Countershaft Fan .....	274015M91	② <b>B89</b>
Belt - Straw Chopper Corn Kit .....	842935M1	<b>C51</b>
Belt - Straw Spreader .....	842110M1	<b>B192</b>
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	<b>C85</b>
<b>Perkins 6-Cyl. 354 Diesel</b>		
<b>1984-1979</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲ <b>9430HD</b>
Belt - Alt.; Ser. No. 1696015715 & Before .....	273837M91	② <b>7570</b>
Belt - Alt.; Ser. No. 1696015716 Thru 1696016538 .....	532779M92	② <b>7520</b>
Belt - Alt.; Ser. No. 1696016539 & After .....	844079M1	▲ <b>9520HD</b>
Belt - Countershaft - Reel .....	834139M1	<b>C71</b>
Belt - Gov. ....	521398M91	<b>7585</b>
Belt - Grain Tank Unloader .....	833873M1	<b>2/B75</b>
Belt - Hyd. Pump; Ser. No. 169605386 & Before .....	222882M2	<b>B60</b>
Belt - Hyd. Pump; Ser. No. 169605387 & After .....	842413M2	<b>B56</b>
Belt - Hydro. Reel Pump .....	842845M1	<b>B78</b>
Belt - Rad. Fan .....	265522M92	② <b>A67</b>
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	<b>C144</b>
Belt - Return Elevator Drive .....	833854M2	<b>B116</b>
Belt - Shaker Shoe .....	273757M91	② <b>B154</b>
Belt - Shaker Shoe Countershaft Fan .....	281560M91	② <b>B90</b>
Belt - Straw Chopper - Rear .....	832906M1	<b>C158</b>
Belt - Straw Chopper Corn Kit .....	842935M1	<b>C51</b>
Belt - Straw Spreader .....	842110M1	<b>B192</b>
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	<b>C85</b>
Hose - Upper - Eng. To Pipe .....		≡ <b>20882</b>
Hose - Upper - Pipe To Rad. ....		<b>24232</b>
Hose - Lower - Eng. To Pipe .....		≡ <b>20611</b>
Hose - Lower - Pipe To Rad. ....		≡ <b>20882</b>
<b>1978</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	843045M1	▲ <b>9451HD</b>
Belt - Alt.; Ser. No. 1696015715 & Before .....	273837M91	② <b>7570</b>
Belt - Alt.; Ser. No. 1696015716 Thru 1696016538 .....	532779M92	② <b>7520</b>
Belt - Alt.; Ser. No. 1696016539 & After .....	844079M1	▲ <b>9520HD</b>
Belt - Countershaft - Reel .....	834139M1	<b>C71</b>
Belt - Gov. ....	521398M91	<b>7585</b>
Belt - Grain Tank Unloader .....	833873M1	<b>2/B75</b>
Belt - Hyd. Pump; Ser. No. 169605386 & Before .....	222882M2	<b>B60</b>
Belt - Hyd. Pump; Ser. No. 169605387 & After .....	842413M2	<b>B56</b>
Belt - Hydro. Reel Pump .....	842845M1	<b>B78</b>
Belt - Rad. Fan .....	265522M92	② <b>A67</b>
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	<b>C144</b>
Belt - Return Elevator Drive .....	833854M2	<b>B116</b>
Belt - Shaker Shoe .....	273757M91	② <b>B154</b>

②Two Required ≡Cut to Fit ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>750SP - Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel - Continued</b>		
<b>1978 - Continued</b>		
Belt - Shaker Shoe Countershaft Fan; Ser. No. 15715 & Before	274015M91	②B89
Belt - Shaker Shoe Countershaft Fan; Ser. No. 15716 & After	281560M91	②B90
Belt - Straw Chopper Corn Kit	842935M1	C51
Belt - Straw Spreader	842110M1	B192
Belt - Wobble Box; W/15-24 Ft. Rigid Bar	834190M1	C85
Hose - Upper - Eng. To Pipe		④<20882
Hose - Upper - Pipe To Rad.		24232
Hose - Lower - Eng. To Pipe		④<20611
Hose - Lower - Pipe To Rad.		④<20882
<b>1977</b>		
Belt - A.C.; W/Frigidaire A.C. Compr.	843045M1	④9451HD
Belt - Air Intake	216897M1	A70
Belt - Alt.; Ser. No. 1696015715 & Before	273837M91	②7570
Belt - Alt.; Ser. No. 1696015716 Thru 1696016538	532779M92	②7520
Belt - Alt.; Ser. No. 1696016539 & After	844079M1	④9520HD
Belt - Countershaft - Reel	834139M1	C71
Belt - Gov.	521398M91	7585
Belt - Grain Tank Unloader	833873M1	2/B75
Belt - Hyd. Pump; Ser. No. 169605386 & Before	222882M2	B60
Belt - Hyd. Pump; Ser. No. 169605387 & After	842413M2	B56
Belt - Hydro. Reel Pump	842845M1	B78
Belt - Rad. Fan	259047M91	②A65
Belt - Reel Drive; W/Fixed Speed Drive	834140M1	C144
Belt - Return Elevator Drive	833854M2	B116
Belt - Shaker Shoe	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan	274015M91	②B89
Belt - Straw Chopper Corn Kit	842935M1	C51
Belt - Straw Spreader	842110M1	B192
Belt - Wobble Box; W/15-24 Ft. Rigid Bar	834190M1	C85
Hose - Upper - Eng. To Pipe		④<20882
Hose - Upper - Pipe To Rad.		24232
Hose - Lower - Eng. To Pipe		④<20611
Hose - Lower - Pipe To Rad.		④<20882
<b>1976-1973</b>		
Belt - Air Intake	216897M1	A70
Belt - Alt.; Ser. No. 1696015715 & Before	273837M91	②7570
Belt - Alt.; Ser. No. 1696015716 Thru 1696016538	532779M92	②7520
Belt - Alt.; Ser. No. 1696016539 & After	844079M1	④9520HD
Belt - Countershaft - Reel	834139M1	C71
Belt - Gov.	521398M91	7585
Belt - Grain Tank Unloader	833873M1	2/B75
Belt - Hyd. Pump; Ser. No. 169605386 & Before	222882M2	B60
Belt - Hyd. Pump; Ser. No. 169605387 & After	842413M2	B56
Belt - Hydro. Reel Pump	842845M1	B78
Belt - Rad. Fan	259047M91	②A65
Belt - Reel Drive; W/Fixed Speed Drive	834140M1	C144
Belt - Return Elevator Drive	833854M2	B116
Belt - Shaker Shoe	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan	274015M91	②B89
Belt - Straw Chopper Corn Kit	842935M1	C51
Belt - Straw Spreader	842110M1	B192
Belt - Wobble Box; W/15-24 Ft. Rigid Bar	834190M1	C85
Hose - Upper - Eng. To Pipe		④<20882
Hose - Upper - Pipe To Rad.		24232
Hose - Lower - Eng. To Pipe		④<20611
Hose - Lower - Pipe To Rad.		④<20882
<b>760SP</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
<b>1983-1980</b>		
Belt - A.C.; W/Frigidaire A.C. Compr.	529964M1	④9430HD
Belt - Alt.	844079M1	④9520HD
Belt - Countershaft - Reel	834139M1	C71
Belt - Grain Tank Unloader	833862M3	B88
Belt - Hyd. Pump	842413M1	B56
Belt - Hydro. Reel Pump	842845M1	B78
Belt - Rad. Fan	259047M91	②A65

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>760SP - Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel - Continued</b>		
<b>1983-1980 - Continued</b>		
Belt - Reel Drive; W/Fixed Speed Drive	834140M1	C144
Belt - Return Elevator Drive	833854M2	B116
Belt - Shaker Shoe	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan	281560M91	②B90
Belt - Straw Chopper - Rear	832906M1	C158
Belt - Straw Spreader	842110M1	B192
Belt - Straw Walker	833860M1	C210
Belt - Wobble Box; W/15-20 Ft. Floating Bar	843029M1	C90
Belt - Wobble Box; W/15-24 Ft. Rigid Bar	834190M1	C85
Belt - Wobble Box; W/20 Ft. Floating Bar	833962M1	C115
Belt - Wobble Box; W/30 Ft. Table	210774M1	C97
Hose - Upper - Eng. To Pipe		④<20206
Hose - Upper - Pipe To Rad.		24232
Hose - Lower - Eng. To Pipe		④<20611
Hose - Lower - Pipe To Rad.		④<20420
		or ●26508
<b>1979</b>		
Belt - A.C.; W/Frigidaire A.C. Compr.	529964M1	④9430HD
Belt - Alt.	844079M1	④9520HD
Belt - Countershaft - Reel	834139M1	C71
Belt - Grain Tank Unloader	833862M3	B88
Belt - Hyd. Pump	842413M1	B56
Belt - Hydro. Reel Pump	842845M1	B78
Belt - Rad. Fan	259047M91	②A65
Belt - Reel Drive; W/Fixed Speed Drive	834140M1	C144
Belt - Return Elevator Drive	833854M2	B116
Belt - Shaker Shoe	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan	281560M91	②B90
Belt - Straw Chopper - Rear	832906M1	C158
Belt - Straw Spreader	842110M1	B192
Belt - Straw Walker	833860M1	C210
Belt - Wobble Box; W/13 Ft. Rigid Bar	834058M1	C84
Belt - Wobble Box; W/15-20 Ft. Floating Bar	843029M1	C90
Belt - Wobble Box; W/15-24 Ft. Rigid Bar	834190M1	C85
Belt - Wobble Box; W/20 Ft. Floating Bar	833962M1	C115
Belt - Wobble Box; W/30 Ft. Table	210774M1	C97
Hose - Upper - Eng. To Pipe		④<20206
Hose - Upper - Pipe To Rad.		24232
Hose - Lower - Eng. To Pipe		④<20611
Hose - Lower - Pipe To Rad.		④<20420
		or ●26508
<b>1978</b>		
Belt - A.C.; W/Frigidaire A.C. Compr.	529964M1	④9430HD
Belt - Air Intake	833867M1	A56
Belt - Alt.	273837M91	②7570
Belt - Countershaft - Reel	834139M1	C71
Belt - Grain Tank Unloader	833862M3	B88
Belt - Hyd. Pump	842413M1	B56
Belt - Hydro. Reel Pump	842845M1	B78
Belt - Rad. Fan	259047M91	②A65
Belt - Reel Drive; W/Fixed Speed Drive	834140M1	C144
Belt - Return Elevator Drive	833854M2	B116
Belt - Shaker Shoe	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan	274015M91	②B89
Belt - Straw Chopper Corn Kit	842935M1	C51
Belt - Straw Spreader	842110M1	B192
Belt - Straw Walker	833860M1	C210
Belt - Wobble Box; W/13 Ft. Rigid Bar	834058M1	C84
Belt - Wobble Box; W/15-24 Ft. Rigid Bar	834190M1	C85
Hose - Upper - Eng. To Pipe		④<20206
Hose - Upper - Pipe To Rad.		24232
Hose - Lower - Eng. To Pipe		④<20611
Hose - Lower - Pipe To Rad.		④<20420
		or ●26508
<b>1977</b>		
Belt - A.C.; W/Frigidaire A.C. Compr.	843045M1	④9451HD
Belt - Air Intake	833867M1	A56
Belt - Alt.	273837M91	②7570
Belt - Countershaft - Reel	834139M1	C71
Belt - Grain Tank Unloader	833862M3	B88
Belt - Hyd. Pump	842413M1	B56
Belt - Hydro. Reel Pump	842845M1	B78
Belt - Rad. Fan	274339M91	②A66
Belt - Reel Drive; W/Fixed Speed Drive	834140M1	C144
Belt - Return Elevator Drive	833854M2	B116

②Two Required ④Cut to Fit ●Flexible Coolant Hose ④Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>760SP - Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel - Continued</b>		
<b>1977 - Continued</b>		
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	274015M91	②B89
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
Belt - Wobble Box; W/13 Ft. Rigid Bar .....	834058M1	C84
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Hose - Upper - Eng. To Pipe .....	≠20206	
Hose - Upper - Pipe To Rad. ....	24232	
Hose - Lower - Eng. To Pipe .....	≠20611	
Hose - Lower - Pipe To Rad. ....	≠20420	
	or	●26508
<b>1976-1975</b>		
Belt - Air Intake .....	833867M1	A56
Belt - Alt. ....	273837M91	②7570
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M1	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Rad. Fan .....	274339M91	②A66
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	274015M91	②B89
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
Hose - Upper - Eng. To Pipe .....	≠20206	
Hose - Upper - Pipe To Rad. ....	24232	
Hose - Lower - Eng. To Pipe .....	≠20611	
Hose - Lower - Pipe To Rad. ....	≠20420	
	or	●26508
<b>1974-1973</b>		
Belt - Air Intake .....	833867M1	A56
Belt - Alt. ....	273837M91	②7570
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	222882M2	B60
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	274015M91	②B89
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
Hose - Upper - Eng. To Pipe .....	≠20206	
Hose - Upper - Pipe To Rad. ....	24232	
Hose - Lower - Eng. To Pipe .....	≠20611	
Hose - Lower - Pipe To Rad. ....	≠20420	
	or	●26508
<b>1972-1971</b>		
Belt - A.C. ....	842463M1	B48
Belt - Air Intake .....	833867M1	A56
Belt - Alt. ....	521398M91	②7580
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842464M2	TR28657
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Rad. Fan - Left Side .....	833869M1	▲9550HD
Belt - Rad. Fan - Right Side .....	833870M1	▲9540HD
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	274015M91	②B89
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
Hose - Upper - Eng. To Pipe .....	≠20206	
Hose - Upper - Pipe To Rad. ....	24232	
Hose - Lower - Eng. To Pipe .....	≠20611	
Hose - Lower - Pipe To Rad. ....	≠20420	
	or	●26508

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>760SP - Continued</b>		
<b>Perkins V-8 540 Diesel</b>		
<b>1983-1982</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲9430HD
Belt - Alt. ....	3040950M91	②A56
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M1	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Rad. Fan .....	259047M91	②A65
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Chopper - Rear .....	832906M1	C158
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	843029M1	C90
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/20 Ft. Floating Bar .....	833962M1	C115
Belt - Wobble Box; W/30 Ft. Table .....	210774M1	C97
<b>1981</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲9430HD
Belt - Alt.; Ser. No. 13172 & Before .....	844163M1	▲9600HD
Belt - Alt.; Ser. No. 13173 & After .....	3040950M91	②A56
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M1	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Rad. Fan .....	259047M91	②A65
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Chopper - Rear .....	832906M1	C158
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	843029M1	C90
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/20 Ft. Floating Bar .....	833962M1	C115
Belt - Wobble Box; W/30 Ft. Table .....	210774M1	C97
<b>1980</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲9430HD
Belt - Alt. ....	844163M1	▲9600HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M1	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Rad. Fan .....	259047M91	②A65
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Chopper - Rear .....	832906M1	C158
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	843029M1	C90
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/20 Ft. Floating Bar .....	833962M1	C115
Belt - Wobble Box; W/30 Ft. Table .....	210774M1	C97
<b>1979</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲9430HD
Belt - Alt. ....	844163M1	▲9600HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M1	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Rad. Fan .....	259047M91	②A65
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Chopper - Rear .....	832906M1	C158
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
Belt - Wobble Box; W/13 Ft. Rigid Bar .....	834058M1	C84
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	843029M1	C90
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85

②Two Required ≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>760SP - Continued</b>		
<b>Perkins V-8 540 Diesel - Continued</b>		
<b>1979 - Continued</b>		
Belt - Wobble Box; W/20 Ft. Floating Bar .....	833962M1	C115
Belt - Wobble Box; W/30 Ft. Table .....	210774M1	C97
<b>1978</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲9430HD
Belt - Air Intake .....	833867M1	A56
Belt - Alt. ....	844163M1	▲9600HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M1	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Rad. Fan .....	259047M91	②A65
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	274015M91	②B89
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
Belt - Wobble Box; W/13 Ft. Rigid Bar .....	834058M1	C84
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
<b>1977</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	843045M1	▲9451HD
Belt - Air Intake .....	833867M1	A56
Belt - Alt. ....	844163M1	▲9600HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M1	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Rad. Fan .....	274339M91	②A66
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	274015M91	②B89
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
Belt - Wobble Box; W/13 Ft. Rigid Bar .....	834058M1	C84
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
<b>1976-1975</b>		
Belt - Air Intake .....	833867M1	A56
Belt - Alt. ....	844163M1	▲9600HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M1	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Rad. Fan .....	274339M91	②A66
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	274015M91	②B89
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
<b>1974-1973</b>		
Belt - Air Intake .....	833867M1	A56
Belt - Alt. ....	844163M1	▲9600HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	222882M2	B60
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	274015M91	②B89
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
<b>1972-1971</b>		
Belt - A.C. ....	842463M1	B48
Belt - Air Intake .....	833867M1	A56
Belt - Alt. ....	844163M1	▲9600HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842464M2	TR28657

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>760SP - Continued</b>		
<b>Perkins V-8 540 Diesel - Continued</b>		
<b>1972-1971 - Continued</b>		
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Rad. Fan - Left Side .....	833869M1	▲9550HD
Belt - Rad. Fan - Right Side .....	833870M1	▲9540HD
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	274015M91	②B89
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Straw Walker .....	833860M1	C210
<b>780</b>		
<b>Chrysler 6-Cyl. 225</b>		
<b>1962-1953</b>		
Belt - Fan .....	K194681	7417
Belt - Gov. ....	K179511	7490
<b>850</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
<b>1990-1986</b>		
Belt - A.C. ....	1614371M1	▲9455HD
Belt - Air Intake .....	844307M1	A75
Belt - Alt. ....	844079M1	▲9520HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833873M1	2/B75
Belt - Hyd. Pump .....	842413M2	B56
Belt - Hydro. Reel Pump - Straw Chopper .....	842845M1	B78
Belt - Oil Cooler Fan .....	844461M1	▲9375HD
Belt - Rad. Fan .....	265522M91	②A67
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Wobble Box; W/15-20 Ft. Floating Bar .....	833962M1	C115
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/22 Ft. Floating Cutter Bar .....	227455M1	C126
Belt - Wobble Box; W/22, 24 Ft. Rigid Cutter Bar .....	210774M1	C97
Hose - Lower - Pipe To Rad. ....		24236
<b>1985</b>		
Belt - A.C. ....	1614371M1	▲9455HD
Belt - Air Intake .....	844307M1	A75
Belt - Alt. ....	844079M1	▲9520HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833873M1	2/B75
Belt - Hyd. Pump .....	842413M2	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Oil Cooler Fan .....	844461M1	▲9375HD
Belt - Rad. Fan .....	265522M91	②A67
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Wobble Box; W/15-20 Ft. Floating Bar .....	833962M1	C115
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/22 Ft. Floating Cutter Bar .....	227455M1	C126
Belt - Wobble Box; W/22, 24 Ft. Rigid Cutter Bar .....	210774M1	C97
Hose - Lower - Pipe To Rad. ....		24236
<b>1984-1983</b>		
Belt - A.C. ....	1614371M1	▲9455HD
Belt - Air Intake .....	844307M1	A75
Belt - Alt. ....	844079M1	▲9520HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833873M1	2/B75
Belt - Hyd. Pump .....	842413M2	B56
Belt - Hydro. Reel Pump - Straw Chopper .....	842845M1	B78
Belt - Oil Cooler Fan .....	844461M1	▲9375HD

②Two Required ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>850 - Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel - Continued</b>		
<b>1984-1983 - Continued</b>		
Belt - Rad. Fan .....	265522M91	②A67
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	833962M1	C115
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/22 Ft. Floating Cutter Bar .....	227455M1	C126
Belt - Wobble Box; W/22, 24 Ft. Rigid Cutter Bar .....	210774M1	C97
Hose - Lower - Pipe To Rad. ....		24236
<b>1982-1981</b>		
Belt - A.C. ....	529964M1	▲9430HD
Belt - Air Intake .....	844307M1	A75
Belt - Alt. ....	844079M1	▲9520HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Grain Tank Unloader .....	833873M1	2/B75
Belt - Hyd. Pump .....	842413M2	B56
Belt - Hydro. Reel Pump - Straw Chopper .....	842845M1	B78
Belt - Oil Cooler Fan .....	844461M1	▲9375HD
Belt - Rad. Fan .....	265522M91	②A67
Belt - Reel Drive; W/Fixed Speed Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Chopper Corn Kit .....	842935M1	C51
Belt - Straw Spreader .....	842110M1	B192
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	833962M1	C115
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/22 Ft. Floating Cutter Bar .....	227455M1	C126
Belt - Wobble Box; W/22, 24 Ft. Rigid Cutter Bar .....	210774M1	C97
Hose - Lower - Pipe To Rad. ....		24236
<b>860</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
<b>1990</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲9430HD
Belt - Alt. ....	844079M1	▲9520HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Countershaft To Rotary Screen .....	844306M1	A53
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M2	B56
Belt - Hydro. Reel Pump - Straw Chopper .....	842845M1	B78
Belt - Oil Cooler Fan .....	3040966M1	▲9395HD
Belt - Rad. Fan .....	284633M91	②A64
Belt - Reel Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Rotary Screen Countershaft To Beater .	833867M1	A56
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Spreader .....	842110M1	B192
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	833962M1	C115
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/22, 24 Ft. Rigid Cutter Bar .....	210774M1	C97
<b>1989-1983</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲9430HD
Belt - Alt. ....	844079M1	▲9520HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Countershaft To Rotary Screen .....	844306M1	A53
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M2	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Oil Cooler Fan .....	3040966M1	▲9395HD
Belt - Rad. Fan .....	284633M91	②A64
Belt - Reel Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Rotary Screen Countershaft To Beater .	833867M1	A56
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Spreader .....	842110M1	B192
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	833962M1	C115
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/22, 24 Ft. Rigid Cutter Bar .....	210774M1	C97

②Two Required ▲Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>860 - Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel - Continued</b>		
<b>1989-1983 - Continued</b>		
Belt - Straw Spreader .....	842110M1	B192
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	833962M1	C115
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/22, 24 Ft. Rigid Cutter Bar .....	210774M1	C97
<b>1982-1981</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲9430HD
Belt - Alt. ....	844079M1	▲9520HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Countershaft To Rotary Screen .....	844306M1	A53
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M2	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Oil Cooler Fan .....	3040966M1	▲9395HD
Belt - Rad. Fan .....	259047M91	②A65
Belt - Reel Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Rotary Screen Countershaft To Beater .	833867M1	A56
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Spreader .....	842110M1	B192
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	833962M1	C115
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/22, 24 Ft. Rigid Cutter Bar .....	210774M1	C97
<b>Perkins V-8 540 Diesel</b>		
<b>1990</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲9430HD
Belt - Alt. & W.P. ....	844163M1	▲9600HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Countershaft To Rotary Screen .....	844306M1	A53
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M2	B56
Belt - Hydro. Reel Pump - Straw Chopper .....	842845M1	B78
Belt - Oil Cooler Fan .....	3040966M1	▲9395HD
Belt - Rad. Fan .....	284633M91	②A64
Belt - Reel Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Rotary Screen Countershaft To Beater .	833867M1	A56
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Spreader .....	842110M1	B192
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	833962M1	C115
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/22, 24 Ft. Rigid Cutter Bar .....	210774M1	C97
<b>1989-1983</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲9430HD
Belt - Alt. & W.P. ....	844163M1	▲9600HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Countershaft To Rotary Screen .....	844306M1	A53
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M2	B56
Belt - Hydro. Reel Pump .....	842845M1	B78
Belt - Oil Cooler Fan .....	3040966M1	▲9395HD
Belt - Rad. Fan .....	284633M91	②A64
Belt - Reel Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Rotary Screen Countershaft To Beater .	833867M1	A56
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Spreader .....	842110M1	B192
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	833962M1	C115
Belt - Wobble Box; W/15-24 Ft. Rigid Bar .....	834190M1	C85
Belt - Wobble Box; W/22, 24 Ft. Rigid Cutter Bar .....	210774M1	C97
<b>1982-1981</b>		
Belt - A.C.; W/Frigidaire A.C. Compr. ....	529964M1	▲9430HD
Belt - Alt. & W.P. ....	844163M1	▲9600HD
Belt - Countershaft - Reel .....	834139M1	C71
Belt - Countershaft To Rotary Screen .....	844306M1	A53
Belt - Grain Tank Unloader .....	833862M3	B88
Belt - Hyd. Pump .....	842413M2	B56
Belt - Hydro. Reel Pump .....	842845M1	B78

Agricultural Equipment



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>860 - Continued</b>		
<b>Perkins V-8 540 Diesel - Continued</b>		
<b>1982-1981 - Continued</b>		
Belt - Oil Cooler Fan .....	3040966M1	▲9395HD
Belt - Rad. Fan .....	259047M91	②A65
Belt - Reel Drive .....	834140M1	C144
Belt - Return Elevator Drive .....	833854M2	B116
Belt - Rotary Screen Countershaft To Beater ..	833867M1	A56
Belt - Shaker Shoe .....	273757M91	②B154
Belt - Shaker Shoe Countershaft Fan .....	281560M91	②B90
Belt - Straw Spreader .....	842110M1	B192
Belt - Wobble Box; W/15-20 Ft. Floating Bar ..	833962M1	C115
Belt - Wobble Box; W/15-24 Ft. Rigid Bar ..	834190M1	C85
Belt - Wobble Box; W/22, 24 Ft. Rigid Cutter Bar .....	210774M1	C97
<b>8560</b>		
<b>Cummins 6-Cyl. 5.9 L Diesel</b>		
<b>1990-1986</b>		
Belt - A.C. ....	525906M1	▲9480HD
Belt - Chopper J.S. ....	227455M1	C126
Belt - Grain Elevator .....	227455M1	C126
Belt - Spreader J.S. ....	227455M1	C126
<b>8570</b>		
<b>Cummins 6-Cyl. 8.3 L Diesel</b>		
<b>1997-1990</b>		
Belt - A.C. ....	531603M1	▲9510HD
Belt - Grain Elevator .....	227455M1	C126
Belt - Spreader J.S. ....	227455M1	C126
<b>8590</b>		
<b>Perkins V-8 640 Diesel</b>		
<b>1990</b>		
Belt - Alt.; <under research> .....	137591M1	7460
Belt - Alt.; W/49 3/8" Belt O.C. ....	186976M1	▲9490HD
Belt - Rotary Screen .....	514891M1	AX80
Belt - Thresher Declutch Drive .....	2404170W1	B100
<b>1989-1985</b>		
Belt - Alt.; W/49 3/8" Belt O.C. ....	186976M1	▲9490HD
Belt - Rotary Screen .....	514891M1	AX80
Belt - Thresher Declutch Drive .....	2404170W1	B100
<b>8780</b>		
<b>Cummins 6-Cyl. 8.3 L Diesel</b>		
<b>1997</b>		
Belt - Chopper .....	71388712	C120
Belt - Fan & A.C. ....	531603M1	▲9510HD
Belt - Grain Elevator .....	227455M1	C126
Belt - Spreader J.S. ....	227455M1	C126
<b>9690</b>		
<b>Cummins 6-Cyl. 8.3 L Diesel</b>		
<b>2008-2006</b>		
Belt - Beater Drive .....	71386352	B173
<b>2005</b>		
Belt - Beater Drive .....	71386352	B173
Belt - Chopper - Rear .....	71388712	C210
<b>2004-2003</b>		
Belt - Beater Drive .....	71386352	B173
Belt - Chopper - Rear .....	71388712	C210
Belt - Grain Elevator .....	227455M1	C126
<b>Sisu 6-Cyl. 513 Diesel</b>		
<b>2008-2007</b>		
Belt - Beater Drive .....	71386352	B173
<b>9720</b>		
<b>Perkins V-8 640 Diesel</b>		
<b>1993-1987</b>		
Belt - Alt.; W/43 1/8" Belt O.C. ....	2403270W1	7425
Belt - Alt.; W/49 3/8" Belt O.C. ....	186976M1	▲9490HD
Belt - Rotary Screen .....	514891M1	AX80
Belt - Thresher Declutch Drive .....	2404170W1	B100

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>9790</b>		
<b>Cummins 6-Cyl. 8.9 L Diesel</b>		
<b>2008-2006</b>		
Belt - A.C. ....	71148120	▲9510HD
Belt - Rotary Screen .....	71396754	A68
Belt - Spreader J.S. ....	227455M1	C126
<b>2005</b>		
Belt - A.C. ....	71148120	▲9510HD
Belt - Chopper - Rear .....	71388712	C210
Belt - Rotary Screen .....	71396754	A68
Belt - Spreader J.S. ....	227455M1	C126
<b>2004-2003</b>		
Belt - A.C. ....	71148120	▲9510HD
Belt - Chopper - Rear .....	71388712	C210
Belt - Grain Elevator .....	227455M1	C126
Belt - Rotary Screen .....	71396754	A68
Belt - Spreader J.S. ....	227455M1	C126
<b>Sisu 6-Cyl. 513 Diesel</b>		
<b>2008-2007</b>		
Belt - A.C. ....	71148120	▲9510HD
Belt - Rotary Screen .....	71396754	A68
Belt - Spreader J.S. ....	227455M1	C126
<b>9895</b>		
<b>Caterpillar C13 Diesel</b>		
<b>2009-2007</b>		
Belt - Rotary Screen .....	71396754	A68
<b>Super 92</b>		
<b>Continental 4-Cyl. 242</b>		
<b>1963-1960</b>		
Belt - Fan .....	220773M1	B94
Belt - Hyd. Pump .....	210716M1	B57
Belt - W.P. & Gen. ....	1506373M1	TR24489
Hose - Upper; Ser. No. 157118 & Before .....		≈20206
Hose - Lower; Ser. No. 157118 & Before .....		≈20065
<b>Perkins 4-Cyl. 302 Diesel</b>		
<b>1963-1960</b>		
Belt - Hyd. Pump .....	227976M1	B54
Belt - W.P. & Gen. ....	1852966M1	▲9530HD
<b>MASSEY HARRIS</b>		
<b>27; 27SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
<b>1952-1949</b>		
Belt - Fan .....	GK5105	B96
<b>60SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
<b>1955-1953</b>		
Belt - Fan; Ser. No. 250299 & Before .....	203052M1	B92
Belt - Fan; Ser. No. 250300 & After .....	213850M1	B90
Belt - Hyd. Pump; Ser. No. 251094 & Before ..	210716M1	B57
Belt - Hyd. Pump; Ser. No. 251095 & After .....	210810M1	B51
Belt - W.P. & Gen. ....	1506373M1	TR24489
<b>80SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
<b>1955-1953</b>		
Belt - Fan; Ser. No. 208479 & After .....	213850M1	B90
Belt - Gov. ....	211740M2	TR22350
Belt - Hyd. Pump; W/Bendix Pump .....	210716M1	B57
Belt - Hyd. Pump; W/Pesco Pump .....	210810M1	B51
Belt - W.P. & Gen. ....	1506373M1	TR24489
<b>82SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
<b>1958</b>		
Belt - Fan .....	213850M1	B90
Belt - Gov. ....	211740M1	TR22350
Belt - Hyd. Pump .....	210810M1	B51
Belt - W.P. & Gen. ....	213850M1	B90

②Two Required ≈Cut to Fit ▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>MASSEY HARRIS - Continued</b>		
<b>90SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1955-1953		
Belt - Fan; Ser. No. 133149 & After .....	213850M1	<b>B90</b>
Belt - Gov. ....	211740M2	<b>TR22350</b>
Belt - Hyd. Pump; W/Bendix Pump .....	210716M1	<b>B57</b>
Belt - Hyd. Pump; W/Pesco Pump .....	210810M1	<b>B51</b>
Belt - W.P. & Gen. ....	1506373M1	<b>TR24489</b>
<b>MINNEAPOLIS-MOLINE</b>		
<b>570 Customatic SP</b>		
<b>Continental 6-Cyl. 226</b>		
1963-1959		
Belt - Fan & Gen. ....	835S	<b>TR20451</b>
<b>2890SP</b>		
<b>Chrysler 6-Cyl. 251</b>		
1971-1964		
Belt - Fan & Gen. ....		<b>TR24489</b>
Belt - Gov. ....		<b>TR22322</b>
Hose - Upper .....		● <b>26521</b>
Hose - Lower .....		● <b>26612</b>
<b>7600SP</b>		
<b>Chrysler V-8 318</b>		
1974-1972		
Belt - Air Compr. ....	311607690	▲ <b>9630HD</b>
Belt - Cleaner Fan .....	W9811480	<b>B110</b>
Belt - Crop Chopper - Front .....	W7532730	<b>C90</b>
Belt - Crop Chopper - Intermediate .....	W7532740	<b>C112</b>
Belt - Fan & Alt. ....	W9811873	<b>7525</b>
Belt - Hydro. Charge Pump .....	311567430	<b>7665</b>
Belt - Hydro. Drive .....	W9811840	<b>2/B162</b>
Belt - Leveling Auger .....	311563120	<b>B144</b>
Belt - Propulsion .....	W9811830	<b>3/B81</b>
Belt - Return Elevator Drive .....	W9811490	<b>B64</b>
Belt - Straw Spreader .....	311568370	<b>B210</b>
Belt - Straw Walker .....	W9811710	<b>B150</b>
Belt - Unloader Countershaft .....	W9811420	<b>2/B64</b>
<b>Chrysler V-8 318 Diesel</b>		
1974-1972		
Belt - Air Compr. ....	311607690	▲ <b>9630HD</b>
Belt - Cleaner Fan .....	W9811480	<b>B110</b>
Belt - Crop Chopper - Front .....	W7532730	<b>C90</b>
Belt - Crop Chopper - Intermediate .....	W7532740	<b>C112</b>
Belt - Fan & Alt. ....	W9811873	<b>7525</b>
Belt - Hydro. Charge Pump .....	311567430	<b>7665</b>
Belt - Hydro. Drive .....	W9811840	<b>2/B162</b>
Belt - Leveling Auger .....	311563120	<b>B144</b>
Belt - Propulsion .....	W9811830	<b>3/B81</b>
Belt - Return Elevator Drive .....	W9811490	<b>B64</b>
Belt - Straw Spreader .....	311568370	<b>B210</b>
Belt - Straw Walker .....	W9811710	<b>B150</b>
Belt - Unloader Countershaft .....	W9811420	<b>2/B64</b>
<b>7800SP</b>		
<b>Chrysler V-8 400</b>		
1974-1972		
Belt - Air Compr. ....	311607690	▲ <b>9630HD</b>
Belt - Cleaner Fan .....	W9811480	<b>B110</b>
Belt - Crop Chopper - Front .....	W7532730	<b>C90</b>
Belt - Crop Chopper - Intermediate .....	W7532740	<b>C112</b>
Belt - Hydro. Charge Pump .....	311567430	<b>7665</b>
Belt - Propulsion .....	W9811830	<b>3/B81</b>
Belt - Rad. Fan .....	311558890	② <b>7495</b>
Belt - Return Elevator Drive .....	W9811490	<b>B64</b>
Belt - Straw Walker .....	W9811710	<b>B150</b>
Belt - Unloader Countershaft .....	311558170	<b>2/B61</b>
Belt - W.P. & Alt. ....	311558900	<b>7465</b>
<b>Chrysler V-8 400 Diesel</b>		
1974-1972		
Belt - Air Compr. ....	311607690	▲ <b>9630HD</b>
Belt - Cleaner Fan .....	W9811480	<b>B110</b>
Belt - Crop Chopper - Front .....	W7532730	<b>C90</b>

Application	OEM No.	Our No.
<b>MINNEAPOLIS-MOLINE - Continued</b>		
<b>7800SP - Continued</b>		
<b>Chrysler V-8 400 Diesel - Continued</b>		
1974-1972 - Continued		
Belt - Crop Chopper - Intermediate .....	W7532740	<b>C112</b>
Belt - Hydro. Charge Pump .....	311567430	<b>7665</b>
Belt - Propulsion .....	W9811830	<b>3/B81</b>
Belt - Rad. Fan .....	311558890	② <b>7495</b>
Belt - Return Elevator Drive .....	W9811490	<b>B64</b>
Belt - Straw Walker .....	W9811710	<b>B150</b>
Belt - Unloader Countershaft .....	311558170	<b>2/B61</b>
Belt - W.P. & Alt. ....	311558900	<b>7465</b>
<b>S</b>		
<b>Continental 6-Cyl. 226</b>		
1954-1953		
Belt - Fan & Gen. ....	835S	<b>TR20451</b>
<b>SP168</b>		
<b>Continental 6-Cyl. 226</b>		
1960-1954		
Belt - Fan & Gen. ....	835S	<b>TR20451</b>
<b>SPR168</b>		
<b>Continental 6-Cyl. 226</b>		
1959-1955		
Belt - Fan & Gen. ....	835S	<b>TR20451</b>
<b>SR</b>		
<b>Continental 6-Cyl. 226</b>		
1953-1952		
Belt - Fan & Gen. ....	835S	<b>TR20451</b>
<b>NEW HOLLAND</b>		
<b>885</b>		
<b>Ford 6-Cyl. 300</b>		
1969		
Belt - Fan .....		▲ <b>9412HD</b>
Belt - W.P. & Alt. ....		<b>7417</b>
Belt - W.P. & Hyd. Pump .....		<b>7450</b>
Hose - Upper .....		⊘ <b>20611</b>
		or ● <b>26510</b>
Hose - Lower - Eng. To Pipe .....		⊘ <b>20957</b>
Hose - Lower - Pipe To Rad. ....		<b>24228</b>
<b>975</b>		
<b>Ford 6-Cyl. 240</b>		
1974-1967		
Belt - Fan .....		▲ <b>9412HD</b>
Belt - W.P. & Alt. ....		<b>7417</b>
Belt - W.P. & Hyd. Pump .....		<b>7450</b>
Hose - Upper .....		⊘ <b>20611</b>
		or ● <b>26510</b>
Hose - Lower - Eng. To Pipe .....		⊘ <b>20957</b>
Hose - Lower - Pipe To Rad. ....		<b>24228</b>
<b>980</b>		
<b>Ford 6-Cyl. 240</b>		
1967-1966		
Belt - Fan .....		▲ <b>9500HD</b>
Belt - Gov. ....		<b>7250</b>
Belt - W.P. & Alt. ....		<b>7430</b>
Hose - Upper .....		● <b>26611</b>
Hose - Lower .....		<b>24228</b>
<b>995</b>		
<b>Ford 6-Cyl. 380 Diesel</b>		
1973-1968		
Belt - Fan & Alt. ....		②▲ <b>9470HD</b>
Belt - Hyd. Pump .....	230043	<b>B55</b>
<b>Ford V-8 391</b>		
1973-1968		
Belt - Fan & Alt. ....		▲ <b>9476HD</b>

②Two Required ⊘Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>995 - Continued</b>		
<b>Ford V-8 391 - Continued</b>		
<b>1973-1968 - Continued</b>		
Belt - Hyd. Pump .....	230043	B55
<b>1400</b>		
<b>Ford 6-Cyl. 300</b>		
<b>1980-1974</b>		
Belt - Alt. & W.P. ....	500599	♣9412HD
Belt - Eng. Fan .....	500595	♣9412HD
Belt - Fan; W/Variable Speed Drive .....	247782	C106
Belt - Fan & Alt. ....	500597	♣9470HD
Belt - Gov. ....	500598	7450
Belt - Hyd. Pump .....	335258	②B55
Belt - Rotary Screen .....	354338	A33
Belt - Tailings Elevator .....	323413	C75
Hose - Upper .....	♣20046	or ●26502
Hose - Lower - Eng. To Pipe .....	●26501	
Hose - Lower - Pipe To Rad. ....		24228
<b>Ford 6-Cyl. 380 Diesel</b>		
<b>1980-1974</b>		
Belt - Alt. & W.P. ....	500599	♣9412HD
Belt - Eng. Fan .....	500595	♣9412HD
Belt - Fan; W/Variable Speed Drive .....	247782	C106
Belt - Fan & Alt. ....	500597	♣9470HD
Belt - Hyd. Pump .....	335258	②B55
Belt - Rotary Screen .....	354338	A33
Belt - Tailings Elevator .....	323413	C75
Hose - Upper .....	20046	or ●26501
Hose - Lower - Eng. To Cooler .....	20357	
Hose - Lower - Pipe To Rad. ....	●26501	
<b>1500</b>		
<b>Caterpillar V-8 573 Diesel</b>		
<b>1980-1973</b>		
Belt - Fan; W/Variable Speed Drive .....	247782	C106
Belt - Gov. ....	500602	7490
Belt - Hyd. Pump .....	335258	②B55
Belt - Rotary Screen .....	354338	A33
Belt - Tailings Elevator .....	323413	C75
<b>Ford V-8 391</b>		
<b>1980-1973</b>		
Belt - Fan; W/Variable Speed Drive .....	247782	C106
Belt - Fan & Alt. ....	500597	♣9470HD
Belt - Gov. ....	500602	7490
Belt - Hyd. Pump .....	335258	②B55
Belt - Rotary Screen .....	354338	A33
Belt - Tailings Elevator .....	323413	C75
<b>CR920</b>		
<b>New Holland 6-Cyl. 7.5 L Diesel</b>		
<b>2004-2002</b>		
Belt - Air Compressor Blow-Off System .....	84061465	♣9605HD
Belt - Rotary Screen Drive Shaft; W/High Speed .....	87323050	②♣9690HD
<b>CR940</b>		
<b>New Holland 6-Cyl. 7.5 L Diesel</b>		
<b>2006-2002</b>		
Belt - Air Compressor Blow-Off System .....	84061465	♣9605HD
Belt - Rotary Screen Drive Shaft; W/High Speed .....	87323050	②♣9690HD

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>CR960</b>		
<b>New Holland 6-Cyl. 7.8 L Diesel</b>		
<b>2006-2002</b>		
Belt - Rotary Screen Drive Shaft; W/High Speed .....	87323050	②♣9690HD
<b>CR970</b>		
<b>New Holland 6-Cyl. 10.3 L Diesel</b>		
<b>2006-2002</b>		
Belt - Rotary Screen Drive Shaft; W/High Speed .....	87323050	②♣9690HD
<b>CR9040; CR9060</b>		
<b>New Holland 6-Cyl. 9.0 L Diesel</b>		
<b>2009-2007</b>		
Belt - Rotary Screen Drive Shaft; W/High Speed .....	87323050	②♣9690HD
<b>CR9070</b>		
<b>New Holland 6-Cyl. 10.3 L Diesel</b>		
<b>2009-2007</b>		
Belt - Rotary Screen Drive Shaft; W/High Speed .....	87323050	②♣9690HD
<b>CX840</b>		
<b>New Holland 6-Cyl. 7.5 L Diesel</b>		
<b>2001</b>		
Belt - Air Compressor Blow-Off System .....	84061465	♣9605HD
<b>CX8070</b>		
<b>New Holland 6-Cyl. 9.0 L Diesel</b>		
<b>2009-2007</b>		
Belt - Serpentine .....	500371653	♣K100640HD
<b>TR70</b>		
<b>Caterpillar 3208 Diesel</b>		
<b>1980-1979</b>		
Belt - A.C. ....	264557	♣9530HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Fan & Alt.; W/Delco Alt. ....	626654	②♣9555HD
Belt - Fan & Alt.; W/Motorola Alt. ....	254084	♣9510HD
Belt - Header .....	246980	D162
Belt - Hyd. Pump .....	248332	②B65
Belt - Rotary Screen .....	696719	A33
Belt - Rotary Screen Drive Shaft .....	246771	A69
Belt - Straw Spreader .....	246727	B195
Belt - Unloader Auger .....	247782	C106
<b>1978-1975</b>		
Belt - A.C. ....	264557	♣9530HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Fan & Alt.; W/Delco Alt. ....	626654	♣9555HD
Belt - Fan & Alt.; W/Motorola Alt. ....	254084	♣9510HD
Belt - Header .....	246980	D162
Belt - Hyd. Pump .....	248332	②B65
Belt - Rotary Screen .....	696719	A33
Belt - Rotary Screen Drive Shaft .....	246771	A69
Belt - Straw Spreader .....	246727	B195
Belt - Unloader Auger .....	247782	C106
<b>Ford 6-Cyl. 363 Diesel</b>		
<b>1980-1975</b>		
Belt - A.C. ....	577240	♣9545HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Fan & Alt. ....	576774	♣9470HD
Belt - Header .....	246980	D162
Belt - Hyd. Pump .....	576772	②B67
Belt - Rotary Screen .....	696719	A33
Belt - Rotary Screen Drive Shaft .....	246771	A69
Belt - Straw Spreader .....	246727	B195
Belt - Unloader Auger .....	247782	C106
Hose - Upper .....		●26511
<b>Ford V-8 361</b>		
<b>1980-1975</b>		
Belt - A.C. ....	264557	♣9530HD

②Two Required ⓈCut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TR70 - Continued</b>		
<b>Ford V-8 361 - Continued</b>		
<b>1980-1975 - Continued</b>		
Belt - Clean Grain Elevator .....	703747	C92
Belt - Fan & Alt. ....	86514610	②▲9465HD
Belt - Gov. ....	266209	▲9510HD
Belt - Header .....	246980	D162
Belt - Hyd. Pump .....	248332	②B65
Belt - Rotary Screen .....	696719	A33
Belt - Rotary Screen Drive Shaft .....	246771	A69
Belt - Straw Spreader .....	246727	B195
Belt - Unloader Auger .....	247782	C106
<b>TR75</b>		
<b>Caterpillar 3208 Diesel</b>		
<b>1985-1984</b>		
Belt - A.C.; W/48 3/8" Belt O.C. ....	259346	▲9480HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan .....	647901	②7508
Belt - Feeder House; W/Fixed Speed Drive ....	621367	C115
Belt - Hyd. Pump .....	248332	②B65
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
Hose - Upper .....		●26512
<b>1983</b>		
Belt - A.C.; W/48 3/8" Belt O.C. ....	259346	▲9480HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan .....	647901	②7508
Belt - Feeder House; W/Fixed Speed Drive ....	621367	C115
Belt - Header; W/168" Drive; Ser. No. 403276 & Before .....	246980	D162
Belt - Hyd. Pump .....	248332	②B65
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
Hose - Upper .....		●26512
<b>1982</b>		
Belt - A.C.; W/48 3/8" Belt O.C. ....	259346	▲9480HD
Belt - A.C.; W/54 7/8" Belt O.C. ....	577240	▲9545HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan .....	647901	②7508
Belt - Feeder House; W/Fixed Speed Drive ....	621367	C115
Belt - Header; W/168" Drive .....	246980	D162
Belt - Hyd. Pump .....	248332	②B65
Belt - Hydro. Charge Pump .....	259477	B66
Belt - Hydro. Drive - Lower; W/122" Drive .....	716414	CX120
Belt - Hydro. Drive - Upper .....	716416	C92
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
Hose - Upper .....		●26512
<b>1981-1980</b>		
Belt - A.C.; W/54 7/8" Belt O.C. ....	577240	▲9545HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan .....	647901	②7508
Belt - Feeder House; W/Fixed Speed Drive ....	621367	C115
Belt - Header; W/168" Drive .....	246980	D162
Belt - Hyd. Pump .....	248332	②B65
Belt - Hydro. Charge Pump .....	259477	B66
Belt - Hydro. Drive - Lower; W/122" Drive .....	716414	CX120
Belt - Hydro. Drive - Upper .....	716416	C92
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
Hose - Upper .....		●26512

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TR75 - Continued</b>		
<b>Caterpillar 3208 Diesel - Continued</b>		
<b>1981-1980 - Continued</b>		
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
Hose - Upper .....		●26512
<b>Ford 6-Cyl. 363 Diesel</b>		
<b>1985-1984</b>		
Belt - A.C.; W/48 3/8" Belt O.C. ....	259346	▲9480HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Feeder House; W/Fixed Speed Drive ....	621367	C115
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
<b>1983</b>		
Belt - A.C.; W/48 3/8" Belt O.C. ....	259346	▲9480HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Feeder House; W/Fixed Speed Drive ....	621367	C115
Belt - Header; W/168" Drive; Ser. No. 403276 & Before .....	246980	D162
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
<b>1982</b>		
Belt - A.C.; W/48 3/8" Belt O.C. ....	259346	▲9480HD
Belt - A.C.; W/54 7/8" Belt O.C. ....	577240	▲9545HD
Belt - Alt. & W.P. ....	772656	▲9590HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Feeder House; W/Fixed Speed Drive ....	621367	C115
Belt - Header; W/168" Drive .....	246980	D162
Belt - Hyd. Pump .....	259477	②B67
Belt - Hydro. Charge Pump .....	259477	B66
Belt - Hydro. Drive - Lower; W/122" Drive .....	716414	CX120
Belt - Hydro. Drive - Upper .....	716416	C92
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
<b>1981-1980</b>		
Belt - A.C.; W/54 7/8" Belt O.C. ....	577240	▲9545HD
Belt - Alt. & W.P. ....	772656	▲9590HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Feeder House; W/Fixed Speed Drive ....	621367	C115
Belt - Header; W/168" Drive .....	246980	D162
Belt - Hyd. Pump .....	259477	②B67
Belt - Hydro. Charge Pump .....	259477	B66
Belt - Hydro. Drive - Lower; W/122" Drive .....	716414	CX120
Belt - Hydro. Drive - Upper .....	716416	C92
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
<b>TR85</b>		
<b>Caterpillar 3208 Diesel</b>		
<b>1985-1984</b>		
Belt - A.C.; W/48 3/8" Belt O.C. ....	259346	▲9480HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan .....	647901	②7508
Belt - Hyd. Pump .....	248332	②B65
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195

②Two Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TR85 - Continued</b>		
<b>Caterpillar 3208 Diesel - Continued</b>		
<b>1985-1984 - Continued</b>		
Belt - Unloader Auger .....	247782	C106
Hose - Upper .....		②<21379
		or ●26511
<b>1983</b>		
Belt - A.C.; W/48 3/8" Belt O.C. ....	259346	▲9480HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan .....	647901	②7508
Belt - Feeder House; W/Fixed Speed Drive; Ser. No. 308000 Thru 404264 .....	621367	C115
Belt - Header; W/168" Drive; Ser. No. 404264 & Before .....	246980	D162
Belt - Hyd. Pump .....	248332	②B65
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
Hose - Upper .....		②<21379
		or ●26511
<b>1982</b>		
Belt - A.C.; W/48 3/8" Belt O.C. ....	259346	▲9480HD
Belt - A.C.; W/53 3/8" Belt O.C. ....	264557	▲9530HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan .....	647901	②7508
Belt - Feeder House; W/Fixed Speed Drive ....	621367	C115
Belt - Header; W/168" Drive .....	246980	D162
Belt - Hyd. Pump .....	248332	②B65
Belt - Hydro. Charge Pump .....	259477	B66
Belt - Hydro. Drive - Upper .....	716416	C92
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
Hose - Upper .....		②<21379
		or ●26511
<b>1981</b>		
Belt - A.C.; W/53 3/8" Belt O.C. ....	264557	▲9530HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan .....	647901	②7508
Belt - Feeder House; W/Fixed Speed Drive ....	621367	C115
Belt - Header; W/168" Drive .....	246980	D162
Belt - Hyd. Pump .....	248332	②B65
Belt - Hydro. Charge Pump .....	259477	B66
Belt - Hydro. Drive - Lower; W/122" Drive .....	716414	CX120
Belt - Hydro. Drive - Upper .....	716416	C92
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106
Hose - Upper .....		②<21379
		or ●26511
<b>1980</b>		
Belt - A.C.; W/53 3/8" Belt O.C. ....	264557	▲9530HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Chopper Beater .....	246727	B195
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan .....	647901	②7508
Belt - Header; W/168" Drive .....	246980	D162
Belt - Hyd. Pump .....	248332	②B65
Belt - Hydro. Charge Pump .....	259477	B66
Belt - Hydro. Drive - Lower; W/122" Drive .....	716414	CX120
Belt - Hydro. Drive - Upper .....	716416	C92
Belt - Rotary Screen - Lower; W/66" Belt O.C. ....	610767	AX64
Belt - Straw Chopper - Rear .....	614040	CX158
Belt - Straw Spreader .....	230143	B195
Belt - Unloader Auger .....	247782	C106

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TR85 - Continued</b>		
<b>Caterpillar 3208 Diesel - Continued</b>		
<b>1980 - Continued</b>		
Hose - Upper .....		②<21379
		or ●26511
<b>TR86</b>		
<b>Caterpillar 3208 Diesel</b>		
<b>1993-1990</b>		
Belt - Alt. ....	572981	▲9430HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan & Hyd. Pump .....	855676	②▲9650HD
Belt - Feeder House; W/Fixed Speed Drive; W/O Small Grain Special .....	621367	②C115
Belt - Hyd. Pump .....	855676	②▲9650HD
Belt - Straw Spreader .....	230143	B195
<b>1989-1988</b>		
Belt - A.C. ....	577240	▲9545HD
Belt - Alt. ....	572981	▲9430HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan & Hyd. Pump .....	855676	②▲9650HD
Belt - Feeder House; W/Fixed Speed Drive; W/O Small Grain Special .....	621367	②C115
Belt - Hyd. Pump .....	855676	②▲9650HD
Belt - Straw Spreader .....	230143	B195
<b>1987</b>		
Belt - A.C.; Ser. No. 527630 & Before .....	259346	▲9480HD
Belt - A.C.; Ser. No. 527631 & After .....	577240	▲9545HD
Belt - Alt.; Ser. No. 527530 & Before .....	626654	②▲9555HD
Belt - Alt.; Ser. No. 527531 & After .....	572981	▲9430HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan; Ser. No. 527530 & Before ....	647901	②7508
Belt - Eng. Fan & Hyd. Pump; Ser. No. 527531 & After .....	855676	②▲9650HD
Belt - Feeder House; W/Fixed Speed Drive; W/O Small Grain Special .....	621367	②C115
Belt - Hyd. Pump; Ser. No. 527530 & Before ..	248332	②B65
Belt - Hyd. Pump; Ser. No. 527531 & After ....	855676	②▲9650HD
Belt - Rotary Screen - Primary; Ser. No. 527530 & Before .....	610767	AX64
Belt - Straw Spreader .....	230143	B195
<b>1986-1985</b>		
Belt - A.C. ....	259346	▲9480HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan .....	647901	②7508
Belt - Feeder House; W/Fixed Speed Drive; W/O Small Grain Special .....	621367	②C115
Belt - Hyd. Pump .....	248332	②B65
Belt - Straw Spreader .....	230143	B195
<b>Ford 6-Cyl. 7.8 L Diesel</b>		
<b>1993-1990</b>		
Belt - Alt. ....	572981	▲9430HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan & Hyd. Pump .....	855676	②▲9650HD
Belt - Feeder House; W/Fixed Speed Drive; W/O Small Grain Special .....	621367	②C115
Belt - Hyd. Pump .....	855676	②▲9650HD
Belt - Straw Spreader .....	230143	B195
<b>1989-1988</b>		
Belt - A.C. ....	577240	▲9545HD
Belt - Alt. ....	572981	▲9430HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan & Hyd. Pump .....	855676	②▲9650HD
Belt - Feeder House; W/Fixed Speed Drive; W/O Small Grain Special .....	621367	②C115
Belt - Hyd. Pump .....	855676	②▲9650HD
Belt - Straw Spreader .....	230143	B195
<b>1987</b>		
Belt - A.C.; Ser. No. 527630 & Before .....	259346	▲9480HD
Belt - A.C.; Ser. No. 527631 & After .....	577240	▲9545HD
Belt - Alt.; Ser. No. 527530 & Before .....	626654	②▲9555HD
Belt - Alt.; Ser. No. 527531 & After .....	572981	▲9430HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan; Ser. No. 527530 & Before ....	647901	②7508

②Two Required <Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TR86 – Continued</b>		
<b>Ford 6-Cyl. 7.8 L Diesel – Continued</b>		
<b>1987 – Continued</b>		
Belt - Eng. Fan & Hyd. Pump; Ser. No. 527531 & After .....	855676	②▲9650HD
Belt - Feeder House; W/Fixed Speed Drive; W/O Small Grain Special .....	621367	②C115
Belt - Hyd. Pump; Ser. No. 527530 & Before ..	248332	②B65
Belt - Hyd. Pump; Ser. No. 527531 & After .....	855676	②▲9650HD
Belt - Rotary Screen; Ser. No. 527530 & Before .....	610767	AX64
Belt - Straw Spreader .....	230143	B195
<b>1986-1985</b>		
Belt - A.C. ....	259346	▲9480HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Eng. Fan .....	647901	②7508
Belt - Feeder House; W/Fixed Speed Drive; W/O Small Grain Special .....	621367	②C115
Belt - Hyd. Pump .....	248332	②B65
Belt - Straw Spreader .....	230143	B195
<b>TR87</b>		
<b>Ford 6-Cyl. 456 Diesel</b>		
<b>1996</b>		
Belt - A.C. ....	577240	▲9545HD
Belt - Alt. ....	577240	②▲9545HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Feeder House; W/Fixed Speed Drive ...	621367	C115
Belt - Hyd. Pump .....	855676	②▲9650HD
Belt - Straw Spreader .....	230143	B195
<b>1995-1993</b>		
Belt - A.C. ....	577240	▲9545HD
Belt - Alt. ....	577240	▲9545HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Feeder House; W/Fixed Speed Drive ...	621367	C115
Belt - Hyd. Pump .....	855676	②▲9650HD
Belt - Straw Spreader .....	230143	B195
<b>TR88</b>		
<b>Genesis 6-Cyl. 456 Diesel</b>		
<b>1998-1996</b>		
Belt - Alt. ....	86513664	▲K080893HD
Belt - Clean Grain Elevator .....	703747	C92
Belt - Rotary Screen - Primary .....	573957	A54
Belt - Straw Spreader .....	230143	B195
<b>TR89</b>		
<b>Genesis 6-Cyl. 456 Diesel</b>		
<b>2000-1999</b>		
Belt - Alt. ....	86570558	▲K080820HD
Belt - Straw Spreader .....	618040	B225
<b>TR95</b>		
<b>Caterpillar 3208 Diesel</b>		
<b>1985</b>		
Belt - A.C. ....	259346	▲9480HD
Belt - Alt. To W.P. ....	626654	②▲9555HD
Belt - Chopper Beater .....	230143	B195
Belt - Eng. Fan .....	768340	②7545
Belt - Feeder House; W/Fixed Speed Drive ...	621367	②C115
Belt - Header .....	246980	D162
Belt - Hyd. Pump .....	624650	②B75
Belt - Rotary Screen - Primary .....	615790	A71
Belt - Straw Spreader .....	618040	B225
Hose - Upper .....	≧21379	or ●26511
<b>1984-1979</b>		
Belt - A.C. ....	264557	▲9530HD
Belt - Alt. To W.P. ....	626654	②▲9555HD
Belt - Chopper Beater .....	230143	B195
Belt - Eng. Fan .....	768340	②7545
Belt - Feeder House; W/Fixed Speed Drive ...	621367	②C115
Belt - Header .....	246980	D162
Belt - Hyd. Pump .....	624650	②B75
Belt - Rotary Screen - Primary .....	615790	A71

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TR95 – Continued</b>		
<b>Caterpillar 3208 Diesel – Continued</b>		
<b>1984-1979 – Continued</b>		
Belt - Straw Spreader .....	618040	B225
Hose - Upper .....	≧21379	or ●26511
<b>TR96</b>		
<b>Caterpillar 3208 Diesel</b>		
<b>1993-1990</b>		
Belt - Chopper Drum .....	230143	B195
Belt - Eng. Fan & Hyd. Pump .....	855676	②▲9650HD
Belt - Straw Spreader .....	618040	B225
<b>1989</b>		
Belt - Alt.; Ser. No. 528156 Thru 530064 .....	572981	▲9430HD
Belt - Chopper Drum .....	230143	B195
Belt - Eng. Fan & Hyd. Pump .....	855676	②▲9650HD
Belt - Straw Spreader .....	618040	B225
<b>1988</b>		
Belt - A.C. ....	259346	▲9480HD
Belt - Alt. ....	572981	▲9430HD
Belt - Chopper Drum .....	230143	B195
Belt - Eng. Fan & Hyd. Pump .....	855676	②▲9650HD
Belt - Feeder House; W/Fixed Speed Drive ...	621367	②C115
Belt - Straw Spreader .....	618040	B225
<b>1987</b>		
Belt - A.C. ....	259346	▲9480HD
Belt - Alt.; Ser. No. 528155 & Before .....	626654	②▲9555HD
Belt - Alt.; Ser. No. 528156 Thru 530064 .....	572981	▲9430HD
Belt - Chopper Drum .....	230143	B195
Belt - Eng. Fan; Ser. No. 528155 & Before ....	768340	②7545
Belt - Eng. Fan & Hyd. Pump; Ser. No. 528156 & After .....	855676	②▲9650HD
Belt - Feeder House; W/Fixed Speed Drive ...	621367	②C115
Belt - Hyd. Pump; Ser. No. 528155 & Before ...	624650	②B75
Belt - Rotary Screen - Primary; Ser. No. 528155 & Before .....	615790	A71
Belt - Straw Spreader .....	618040	B225
<b>1986-1985</b>		
Belt - A.C. ....	259346	▲9480HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Chopper Drum .....	230143	B195
Belt - Eng. Fan .....	768340	②7545
Belt - Feeder House; W/Fixed Speed Drive ...	621367	②C115
Belt - Hyd. Pump .....	624650	②B75
Belt - Rotary Screen - Primary .....	615790	A71
Belt - Straw Spreader .....	618040	B225
<b>Ford 6-Cyl. 7.8 L Diesel</b>		
<b>1993-1990</b>		
Belt - Chopper Drum .....	230143	B195
Belt - Eng. Fan & Hyd. Pump .....	855676	②▲9650HD
Belt - Straw Spreader .....	618040	B225
<b>1989</b>		
Belt - Alt.; Ser. No. 528156 Thru 530064 .....	572981	▲9430HD
Belt - Chopper Drum .....	230143	B195
Belt - Eng. Fan & Hyd. Pump .....	855676	②▲9650HD
Belt - Straw Spreader .....	618040	B225
<b>1988</b>		
Belt - A.C. ....	259346	▲9480HD
Belt - Alt. ....	572981	▲9430HD
Belt - Chopper Drum .....	230143	B195
Belt - Eng. Fan & Hyd. Pump .....	855676	②▲9650HD
Belt - Feeder House; W/Fixed Speed Drive ...	621367	②C115
Belt - Straw Spreader .....	618040	B225
<b>1987</b>		
Belt - A.C. ....	259346	▲9480HD
Belt - Chopper Drum .....	230143	B195
Belt - Eng. Fan; Ser. No. 528155 & Before ....	768340	②7545
Belt - Eng. Fan & Hyd. Pump; Ser. No. 528156 & After .....	855676	②▲9650HD
Belt - Feeder House; W/Fixed Speed Drive ...	621367	②C115
Belt - Hyd. Pump; Ser. No. 528155 & Before ..	624650	②B75
Belt - Rotary Screen - Primary; Ser. No. 528155 & Before .....	615790	A71
Belt - Straw Spreader .....	618040	B225

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TR96 – Continued</b>		
<b>Ford 6–Cyl. 7.8 L Diesel – Continued</b>		
1986–1985		
Belt - A.C. ....	259346	▲9480HD
Belt - Alt. ....	626654	②▲9555HD
Belt - Chopper Drum ....	230143	B195
Belt - Eng. Fan ....	768340	②7545
Belt - Feeder House, W/Fixed Speed Drive ....	621367	②C115
Belt - Hyd. Pump ....	624650	②B75
Belt - Rotary Screen - Primary ....	615790	A71
Belt - Straw Spreader ....	618040	B225
<b>TR98</b>		
<b>Genesis 6–Cyl. 456 Diesel</b>		
1999–1996		
Belt - A.C. ....	9842660S	▲9570HD
Belt - Fan & Alt. ....	86513664	▲K080893HD
Belt - Hyd. Pump ....	772656	②▲9590HD
<b>TR99</b>		
<b>Genesis 6–Cyl. 456 Diesel</b>		
2000–1999		
Belt - Alt. ....	86570558	▲K080820HD
Belt - Straw Spreader ....	618040	B225
<b>TX66</b>		
<b>Ford 6–Cyl. 456 Diesel</b>		
2001–1998		
Tensioner Assy. ....	86013886	38514
Tensioner Pulley ....	86013886	36091
1997–1993		
Belt - Accessory Drive ....	9835683	▲K080897HD
<b>NEW IDEA</b>		
<b>702</b>		
<b>GM V-6 401</b>		
1971–1966		
Hose - Upper ....		●26511
Hose - Lower ....		●26536
<b>702D</b>		
<b>GMC V-6 478 Diesel</b>		
1971–1967		
Belt - Fan & Alt. ....	703345	▲9605HD
Belt - Fan & Hyd. Pump ....	703346	②▲9690HD
<b>707</b>		
<b>Perkins 6–Cyl. 354 Diesel</b>		
1978–1975		
Belt - Fan & Alt. ....		②▲9525HD
Hose - Upper ....		●26505
<b>710</b>		
<b>Chrysler 6–Cyl. 225</b>		
1974–1965		
Hose - Upper ....		●25476
<b>717</b>		
<b>Perkins 6–Cyl. 354 Diesel</b>		
1981–1974		
Belt - W.P. To Alt. ....	706239	②▲9540HD
<b>800</b>		
<b>Perkins 6–Cyl. 354 Diesel</b>		
1983–1980		
Belt - W.P. To Alt. ....	706239	②▲9540HD
<b>800C</b>		
<b>Cummins 6–Cyl. 505 Diesel</b>		
1991–1984		
Belt - A.C. ....		▲9530HD

Application	OEM No.	Our No.
<b>NEW IDEA - Continued</b>		
<b>800C – Continued</b>		
<b>Cummins 6–Cyl. 505 Diesel – Continued</b>		
1991–1984 – Continued		
Belt - Fan ....		②▲9720HD
<b>803A</b>		
<b>Allis–Chalmers 6–Cyl. 426 Diesel</b>		
1984–1983		
Belt - Fan ....		▲9430HD
Belt - W.P. & Alt. ....		TR22625
Hose - Upper ....		②24236
Hose - Lower ....		②24236
<b>OLIVER</b>		
<b>33</b>		
<b>Continental 6–Cyl. 226</b>		
1954–1950		
Belt - Fan; Ser. No. 300001 Thru 300301 ....	CO9567	TR24461
Belt - Fan; Ser. No. 300302 & After ....	CO9839	TR24476
Hose - Upper; Ser. No. 300001 Thru 300301 ....		●25478
Hose - Lower; Ser. No. 300302 Thru 302301 ....		≈<20065
<b>35</b>		
<b>Continental 6–Cyl. 266</b>		
1959–1954		
Belt - Fan ....	CO9839	TR24476
Belt - P.S. ....	CO11397	▲9390HD
Hose - Upper ....		●25478
Hose - Lower ....		≈<20065
<b>40</b>		
<b>Continental 6–Cyl. 226</b>		
1960–1957		
Belt - Fan & W.P.; Ser. No. 400001 Thru 403702 ....	CO9839	TR24476
Belt - Fan & W.P.; Ser. No. 403703 & After ....	404274D	TR24476
Hose - Upper; Ser. No. 400001 Thru 401001 ....		●25478
Hose - Upper; Ser. No. 401002 Thru 401802 ....		●25476
Hose - Lower; Ser. No. 400001 Thru 401802 ....		≈<20065
<b>Continental 6–Cyl. 226 Diesel</b>		
1960–1957		
Belt - Fan ....	K372	TR22380
Hose - Upper ....		≈<20065
<b>525</b>		
<b>Chrysler 6–Cyl.</b>		
1970–1964		
Belt - Fan & Gen. ....	MXS1668	TR24489
Belt - Gov. ....	MXS1495	TR22329
Hose - Upper ....		●26521
Hose - Lower ....		●25484
<b>535</b>		
<b>Chrysler 6–Cyl. 265</b>		
1970–1965		
Belt - Fan & Gen. ....	MXS1668	TR24489
Belt - Gov. ....	MXS1495	TR22329
Hose - Upper ....		●26521
Hose - Lower ....		●25484
<b>545</b>		
<b>Chrysler 6–Cyl. 265</b>		
1970–1966		
Belt - Fan & Alt. ....	9811683	②▲9545HD
Belt - Fan & Gen. ....	MXS1668	TR24489
Belt - Gov. ....	MXS1495	TR22329
Hose - Upper ....		●25484
Hose - Lower ....		●25484
Hose - By Pass ....		28442

②Two Required ≈<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>5542</b>		
<b>Chrysler V-8 318</b>		
1976-1969		
Belt - Fan & Alt. ....		②7541
Hose - Upper .....		●25487
Hose - By Pass .....		<20563
<b>5555</b>		
<b>Chrysler V-8 318</b>		
1970-1968		
Belt - Cleaner Fan .....	W9811480	<b>B110</b>
Belt - Fan & Alt. ....	W9811873	<b>7525</b>
Belt - Hydro. Drive .....	W9811840	<b>2/B162</b>
Belt - Propulsion .....	W9811830	<b>3/B81</b>
Belt - Rad. Fan .....	311558890	<b>7495</b>
Belt - Return Elevator Drive .....	W9811490	<b>B64</b>
Belt - Straw Walker .....	W9811710	<b>B150</b>
Belt - Unloader Countershaft .....	W9811420	<b>2/B64</b>
Belt - W.P. & Alt. ....	311558900	<b>7465</b>
<b>7300</b>		
<b>Chrysler V-8 318</b>		
1976-1972		
Belt - Fan & Alt.; W/Hydro. Drive .....	311610590	▲9500HD
Belt - Fan & Alt.; W/O Hydro. Drive .....	W9811683	②▲9545HD
Belt - Grain Elevator & Loader; S & D .....	W9811190	<b>C109</b>
Belt - Straw Chopper - Front .....	W7530250	<b>C144</b>
Belt - Straw Spreader .....	W9810640	<b>B168</b>
<b>Perkins 6-Cyl. 354 Diesel</b>		
1976-1972		
Belt - Fan & Alt.; W/Hydro. Drive .....	311610590	▲9500HD
Belt - Fan & Alt.; W/O Hydro. Drive .....	W9811683	②▲9545HD
Belt - Grain Elevator & Loader; S & D .....	W9811190	<b>C109</b>
Belt - Hyd. Pump .....	311809650	▲9355HD
Belt - Straw Chopper - Front .....	W7530250	<b>C144</b>
Belt - Straw Spreader .....	W9810640	<b>B168</b>
<b>WHITE</b>		
<b>5542SP</b>		
<b>Chrysler V-8 318</b>		
1982-1969		
Belt - Fan & Alt. ....	9811670	②▲9540HD
<b>Chrysler V-8 318 Diesel</b>		
1982-1969		
Belt - Fan & Alt. ....	9811670	②▲9540HD
<b>7300SP</b>		
<b>Chrysler V-8 318</b>		
1981-1972		
Belt - Fan & Alt.; W/Hydro. Drive .....	311610590	▲9500HD
Belt - Fan & Alt.; W/O Hydro. Drive .....	W9811683	②▲9545HD
Belt - Grain Elevator & Loader; S & D .....	W9811190	<b>C109</b>
Belt - Straw Chopper - Front .....	W7530250	<b>C144</b>
Belt - Straw Spreader .....	W9810640	<b>B168</b>
<b>Perkins 6-Cyl. 354 Diesel</b>		
1981-1972		
Belt - Fan & Alt.; W/Hydro. Drive .....	311610590	▲9500HD
Belt - Fan & Alt.; W/O Hydro. Drive .....	W9811683	②▲9545HD
Belt - Grain Elevator & Loader; S & D .....	W9811190	<b>C109</b>
Belt - Hyd. Pump .....	311809650	▲9355HD
Belt - Straw Chopper - Front .....	W7530250	<b>C144</b>
Belt - Straw Spreader .....	W9810640	<b>B168</b>
<b>7600SP</b>		
<b>Chrysler V-8 318</b>		
1981-1972		
Belt - Air Compr. ....	311607690	▲9630HD
Belt - Cleaner Fan .....	W9811480	<b>B110</b>
Belt - Crop Chopper - Front .....	W7532730	<b>C90</b>
Belt - Crop Chopper - Intermediate .....	W7532740	<b>C112</b>
Belt - Hydro. Charge Pump .....	311567430	<b>7665</b>
Belt - Propulsion .....	W9811830	<b>3/B81</b>
Belt - Rad. Fan .....	311558890	②7495
Belt - Return Elevator Drive .....	W9811490	<b>B64</b>
Belt - Straw Walker .....	W9811710	<b>B150</b>
Belt - Unloader Countershaft .....	311558170	<b>2/B61</b>
Belt - W.P. & Alt. ....	311558900	<b>7465</b>

Application	OEM No.	Our No.
<b>WHITE - Continued</b>		
<b>7600SP - Continued</b>		
<b>Chrysler V-8 318 - Continued</b>		
1981-1972 - Continued		
Belt - Hydro. Drive .....	W9811840	<b>2/B162</b>
Belt - Leveling Auger .....	311563120	<b>B144</b>
Belt - Propulsion .....	W9811830	<b>3/B81</b>
Belt - Return Elevator Drive .....	W9811490	<b>B64</b>
Belt - Straw Spreader .....	311568370	<b>B210</b>
Belt - Straw Walker .....	W9811710	<b>B150</b>
Belt - Unloader Countershaft .....	W9811420	<b>2/B64</b>
<b>Chrysler V-8 318 Diesel</b>		
1981-1972		
Belt - Air Compr. ....	311607690	▲9630HD
Belt - Cleaner Fan .....	W9811480	<b>B110</b>
Belt - Crop Chopper - Front .....	W7532730	<b>C90</b>
Belt - Crop Chopper - Intermediate .....	W7532740	<b>C112</b>
Belt - Fan & Alt. ....	W9811873	<b>7525</b>
Belt - Hydro. Charge Pump .....	311567430	<b>7665</b>
Belt - Hydro. Drive .....	W9811840	<b>2/B162</b>
Belt - Leveling Auger .....	311563120	<b>B144</b>
Belt - Propulsion .....	W9811830	<b>3/B81</b>
Belt - Return Elevator Drive .....	W9811490	<b>B64</b>
Belt - Straw Spreader .....	311568370	<b>B210</b>
Belt - Straw Walker .....	W9811710	<b>B150</b>
Belt - Unloader Countershaft .....	W9811420	<b>2/B64</b>
<b>7800SP</b>		
<b>Chrysler V-8 400</b>		
1975-1972		
Belt - Air Compr. ....	311607690	▲9630HD
Belt - Cleaner Fan .....	W9811480	<b>B110</b>
Belt - Crop Chopper - Front .....	W7532730	<b>C90</b>
Belt - Crop Chopper - Intermediate .....	W7532740	<b>C112</b>
Belt - Hydro. Charge Pump .....	311567430	<b>7665</b>
Belt - Propulsion .....	W9811830	<b>3/B81</b>
Belt - Rad. Fan .....	311558890	②7495
Belt - Return Elevator Drive .....	W9811490	<b>B64</b>
Belt - Straw Walker .....	W9811710	<b>B150</b>
Belt - Unloader Countershaft .....	311558170	<b>2/B61</b>
Belt - W.P. & Alt. ....	311558900	<b>7465</b>
<b>Chrysler V-8 400 Diesel</b>		
1975-1972		
Belt - Air Compr. ....	311607690	▲9630HD
Belt - Cleaner Fan .....	W9811480	<b>B110</b>
Belt - Crop Chopper - Front .....	W7532730	<b>C90</b>
Belt - Crop Chopper - Intermediate .....	W7532740	<b>C112</b>
Belt - Hydro. Charge Pump .....	311567430	<b>7665</b>
Belt - Propulsion .....	W9811830	<b>3/B81</b>
Belt - Rad. Fan .....	311558890	②7495
Belt - Return Elevator Drive .....	W9811490	<b>B64</b>
Belt - Straw Walker .....	W9811710	<b>B150</b>
Belt - Unloader Countershaft .....	311558170	<b>2/B61</b>
Belt - W.P. & Alt. ....	311558900	<b>7465</b>
<b>8600</b>		
<b>Chrysler V-8 318</b>		
1978-1974		
Belt - A.C. ....	311679590	▲9480HD
Belt - Cleaner Fan; W/Regular Speed Fan .....	9811480	<b>B110</b>
Belt - Countershaft, Hyd. Pump & A.C. Compr. ....	311677220	▲9530HD
Belt - Crop Chopper - Front .....	W7532730	<b>C90</b>
Belt - Crop Chopper - Intermediate .....	W7532740	<b>C112</b>
Belt - Hyd. Pump .....	311681440	▲9570HD
Belt - Hydro. Pump .....	311567430	<b>7665</b>
Belt - Leveling Auger .....	311680230	<b>B230</b>
Belt - Rad. Fan .....	311677150	②7410
Belt - Return Elevator Drive .....	W9811490	<b>B64</b>
Belt - Rotary Screen .....	311764410	<b>A76</b>
Belt - Straw Spreader .....	311568370	<b>B210</b>
Belt - Straw Walker .....	W9811710	<b>B150</b>
Belt - Unloader Declutch Drive .....	311669560	<b>2/B75</b>
Belt - W.P. & Alt. ....	311683780	▲9476HD

②Two Required <Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>WHITE - Continued</b>		
<b>8600 – Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1978-1974		
Belt - A.C. ....	311679590	▲9480HD
Belt - Cleaner Fan; W/Regular Speed Fan ....	9811480	B110
Belt - Countershaft, Hyd. Pump & A.C. Compr. ....	311677220	▲9530HD
Belt - Crop Chopper - Front .....	W7532730	C90
Belt - Crop Chopper - Intermediate .....	W7532740	C112
Belt - Hyd. Pump .....	311681440	▲9570HD
Belt - Hydro. Pump .....	311567430	7665
Belt - Leveling Auger .....	311680230	B230
Belt - Rad. Fan .....	311677150	②7410
Belt - Return Elevator Drive .....	W9811490	B64
Belt - Rotary Screen .....	311764410	A76
Belt - Straw Spreader .....	311568370	B210
Belt - Straw Walker .....	W9811710	B150
Belt - Unloader Declutch Drive .....	311669560	2/B75
Belt - W.P. & Alt. ....	311774180	▲9530HD
<b>8700</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1982-1979		
Belt - A.C. ....	311679590	▲9480HD
Belt - Cleaner Fan; W/Regular Speed Fan ....	9811480	B110
Belt - Cleaner Fan; W/Slow Speed Fan .....	311567900	B104
Belt - Countershaft - Slow Speed .....	311825840	B158
Belt - Countershaft, Hyd. Pump & A.C. Compr. ....	311803500	▲9540HD
Belt - Crop Chopper - Intermediate .....	W7532740	C112
Belt - Hyd. Pump .....	311710550	▲9570HD
Belt - Hydro. Pump .....	311567430	7665
Belt - Rad. Fan .....	311677150	②7410
Belt - Return Elevator Drive .....	W9811490	B64
Belt - Rotary Screen .....	311764410	A76
Belt - Straw Spreader .....	311568370	B210
Belt - Straw Walker .....	W9811710	B150
Belt - Unloader Declutch Drive .....	311732180	2/B90
Belt - W.P. & Alt. ....	311774180	▲9530HD
<b>8700HB</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1984-1982		
Belt - Hydro. Pump .....	311567430	7665
<b>8800</b>		
<b>Chrysler V-8 400</b>		
1977-1974		
Belt - A.C. ....	311679590	▲9480HD
Belt - Cleaner Fan; W/Regular Speed Fan ....	9811480	B110
Belt - Countershaft, Hyd. Pump & A.C. Compr. ....	311677220	▲9530HD
Belt - Crop Chopper - Front .....	W7532730	C90
Belt - Crop Chopper - Intermediate .....	W7532740	C112
Belt - Hyd. Pump .....	311681440	▲9570HD
Belt - Hydro. Pump .....	311567430	7665
Belt - Rad. Fan .....	311677150	②7410
Belt - Return Elevator Drive .....	W9811490	B64
Belt - Rotary Screen .....	311764410	A76
Belt - Straw Walker .....	W9811710	B150
Belt - Unloader Declutch Drive .....	311669560	2/B75
Belt - W.P. & Alt. ....	311558900	7465
<b>Perkins 6-Cyl. 354 Diesel</b>		
1977-1974		
Belt - A.C. ....	311679590	▲9480HD
Belt - Cleaner Fan; W/Regular Speed Fan ....	9811480	B110
Belt - Countershaft, Hyd. Pump & A.C. Compr. ....	311677220	▲9530HD
Belt - Crop Chopper - Front .....	W7532730	C90
Belt - Crop Chopper - Intermediate .....	W7532740	C112
Belt - Hyd. Pump .....	311681440	▲9570HD
Belt - Hydro. Pump .....	311567430	7665
Belt - Rad. Fan .....	311677150	②7410
Belt - Return Elevator Drive .....	W9811490	B64
Belt - Rotary Screen .....	311764410	A76
Belt - Straw Walker .....	W9811710	B150
Belt - Unloader Declutch Drive .....	311669560	2/B75

Application	OEM No.	Our No.
<b>WHITE - Continued</b>		
<b>8800 – Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel – Continued</b>		
1977-1974 – Continued		
Belt - W.P. & Alt. ....	311774180	▲9530HD
<b>8900</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1984-1979		
Belt - A.C. ....	311679590	▲9480HD
Belt - Chopper - Primary .....	317535040	C150
Belt - Cleaner Fan; W/Regular Speed Fan ....	9811480	B110
Belt - Cleaner Fan; W/Slow Speed Fan .....	311567900	B104
Belt - Hyd. Pump .....	311710550	▲9570HD
Belt - Hyd. Pump & A.C. Compr. ....	311803500	▲9540HD
Belt - Hydro. Pump .....	311567430	7665
Belt - Propulsion - Hydro. Drive .....	311669610	③B190
Belt - Rad. Fan .....	311677150	7410
Belt - Return Elevator Drive .....	W9811490	B64
Belt - Rotary Screen .....	311764410	A76
Belt - Straw Walker .....	9811710	B150
Belt - Unloader Declutch Drive .....	311732180	2/B90
Belt - W.P. & Alt. ....	311774180	▲9530HD
Hose - Upper .....		≈<20206
1978		
Belt - A.C. ....	311679590	▲9480HD
Belt - Chopper - Primary .....	317535040	C150
Belt - Cleaner Fan; W/Regular Speed Fan ....	9811480	B110
Belt - Cleaner Fan; W/Slow Speed Fan .....	311567900	B104
Belt - Hyd. Pump .....	311710550	▲9570HD
Belt - Hyd. Pump & A.C. Compr.; Ser. No. 21100 & Before .....	311677220	▲9530HD
Belt - Hyd. Pump & A.C. Compr.; Ser. No. 21101 & After .....	311803500	▲9540HD
Belt - Hydro. Pump .....	311567430	7665
Belt - Propulsion - Hydro. Drive .....	311669610	③B190
Belt - Rad. Fan .....	311677150	7410
Belt - Return Elevator Drive .....	W9811490	B64
Belt - Rotary Screen .....	311764410	A76
Belt - Straw Walker .....	9811710	B150
Belt - Unloader Declutch Drive .....	311732180	2/B90
Belt - W.P. & Alt. ....	311774180	▲9530HD
Hose - Upper .....		≈<20206
<b>8920</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1987-1985		
Belt - A.C. ....	311679590	▲9480HD
Belt - Cleaner Fan; W/Regular Speed Fan ....	9811480	B110
Belt - Cleaner Fan; W/Slow Speed Fan .....	311567900	B104
Belt - Hyd. Pump .....	311710550	▲9570HD
Belt - Hydro. Pump .....	311567430	7665
Belt - Propulsion - Hydro. Drive .....	311669610	③B190
Belt - Propulsion - Mechanical; W/Variable Speed Drive .....	317535040	C150
Belt - Rad. Fan .....	311677150	7410
Belt - Reel Drive - Final; W/Variable Speed Drive .....	311831290	B158
Belt - Return Elevator Drive .....	W9811490	B64
Belt - Rotary Screen .....	311764410	A76
Belt - Straw Walker .....	9811710	B150
Belt - Unloader Declutch Drive .....	311732180	2/B90
Belt - W.P. & Alt. ....	311774180	▲9530HD
1984		
Belt - A.C. ....	311679590	▲9480HD
Belt - Chopper - Primary .....	317535040	C150
Belt - Cleaner Fan; W/Regular Speed Fan ....	9811480	B110
Belt - Cleaner Fan; W/Slow Speed Fan .....	311567900	B104
Belt - Hyd. Pump .....	311710550	▲9570HD
Belt - Hydro. Pump .....	311567430	7665
Belt - Propulsion - Hydro. Drive .....	311669610	③B190
Belt - Propulsion - Mechanical; W/Variable Speed Drive .....	317535040	C150
Belt - Rad. Fan .....	311677150	7410
Belt - Reel Drive - Final; W/Variable Speed Drive .....	311831290	B158
Belt - Return Elevator Drive .....	W9811490	B64
Belt - Rotary Screen .....	311764410	A76
Belt - Straw Spreader .....	311831290	B158

②Two Required ③Three Required ≈<Cut to Fit ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>WHITE - Continued</b>		
<b>8920 – Continued</b>		
<b>Perkins 6-Cyl. 354 Diesel – Continued</b>		
<b>1984 – Continued</b>		
Belt - Straw Walker .....	9811710	<b>B150</b>
Belt - Unloader Declutch Drive .....	311732180	<b>2/B90</b>
Belt - W.P. & Alt. ....	311774180	<b>▲9530HD</b>
<b>9700</b>		
<b>Perkins V-8 640 Diesel</b>		
<b>1984-1979</b>		
Belt - A.C. ....	312498110	<b>▲9463HD</b>
Belt - Alt. ....	312403270	<b>7425</b>
Belt - Chopper .....	312456600	<b>C72</b>
Belt - Hyd. Pump .....	312549250	<b>B53</b>
Belt - Return Elevator Drive .....	312492070	<b>B66</b>
Belt - Rotary Screen .....	312448930	<b>A80</b>
Belt - Thresher Declutch Drive .....	312404170	<b>BP100</b>
Belt - W.P. ....	312414670	<b>▲9490HD</b>
Hose - Upper .....		<b>●26532</b>
<b>9720</b>		
<b>Perkins V-8 640 Diesel</b>		
<b>1987-1984</b>		
Belt - A.C. ....	312498110	<b>▲9463HD</b>
Belt - Alt. ....	312403270	<b>7425</b>
Belt - Hyd. Pump .....	312604010	<b>6973</b>
Belt - Return Elevator Drive .....	312492070	<b>B66</b>
Belt - Rotary Screen .....	312448930	<b>A80</b>
Belt - Straw Spreader - Upper .....	312543960	<b>B69</b>
Belt - Thresher Declutch Drive .....	312404170	<b>BP100</b>
Belt - W.P. ....	312414670	<b>▲9490HD</b>

●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Manufacturers' Part Number Shown for Reference Only

Application	OEM No.	Our No.	Application	OEM No.	Our No.
<b>ALLIS-CHALMERS</b>			<b>ALLIS-CHALMERS - Continued</b>		
<b>500</b>			<b>801; 802 – Continued</b>		
<b>Allis-Chalmers 4-Cyl. 226</b>			<b>Allis-Chalmers 6-Cyl. 262 Diesel</b>		
1960-1958			1969-1966		
Belt - Fan .....	229211	▲9463HD	Belt - Fan .....	227470	▲9480HD
Hose - Upper; Early .....		☞20088	Belt - P.S. ....	826215	▲9425HD
		or ●25474			
Hose - Lower; Early .....		☞21794			
		or ●25476			
<b>Allis-Chalmers 6-Cyl. 262 Diesel</b>			<b>860</b>		
1960-1958			<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
Belt - Fan .....	229559	▲9455HD	1978-1973		
			Belt - Alt./Gen. ....	582884	▲9550HD
			Belt - Gov.; Ser. No. 4000 & Before .....	1146702	7480
			Belt - Hyd. Pump .....	582377	TR28463
			Hose - Upper .....		●26505
			Hose - By Pass .....		☞20563
<b>616 Cotton Picker</b>			<b>860XTB</b>		
<b>Allis-Chalmers 6-Cyl. 262</b>			<b>Chevrolet 6-Cyl. 250</b>		
1965-1961			1978-1973		
Belt - Fan; Ser. No. 68068 & Before .....	229211	▲9463HD	Belt - Alt./Gen. ....	1146660	7400
Belt - Fan; Ser. No. 68069 & After .....	237048	▲9455HD	Belt - Gov.; Ser. No. 4000 & Before .....	1146702	7480
Belt - P.S. ....	826215	▲9425HD	Belt - Hyd. Pump .....	562203	▲9440HD
Hose - Upper; Early .....		☞20088			
		or ●25474			
Hose - Lower; Early .....		☞21794			
		or ●25476			
<b>Allis-Chalmers 6-Cyl. 262 Diesel</b>			<b>880</b>		
1965-1961			<b>Allis-Chalmers 4-Cyl. 200 Diesel</b>		
Belt - Fan; Ser. No. 250 & Before .....	229559	②▲9455HD	1984-1980		
Belt - Fan; Ser. No. 251 & After .....	227470	▲9480HD	Belt - A.C. ....	1148120	▲9510HD
Belt - P.S. ....	826215	▲9425HD	Belt - Alt.; W/53 1/4" Belt O.C. ....		▲9530HD
Hose - Upper; Early .....		●25473	Belt - Alt.; W/54 1/4" Belt O.C. ....		▲9540HD
Hose - Lower; Early .....		24224	Belt - Hyd. Pump .....	1173232	▲9640HD
<b>622</b>			<b>Two Row</b>		
<b>Allis-Chalmers 6-Cyl. 262</b>			<b>Allis-Chalmers 4-Cyl. 226</b>		
1965-1960			1958-1949		
Belt - Fan; Ser. No. 68068 & Before .....	229211	▲9463HD	Belt - Fan .....	229211	▲9463HD
Belt - Fan; Ser. No. 68069 & After .....	237048	▲9455HD	Hose - Upper .....		24224
Belt - P.S. ....	826215	▲9425HD	Hose - Lower .....		24224
Hose - Upper; Early .....		☞20088			
		or ●25474			
Hose - Lower; Early .....		☞21794			
		or ●25476			
<b>Allis-Chalmers 6-Cyl. 262 Diesel</b>			<b>Allis-Chalmers 4-Cyl. 226 Diesel</b>		
1965-1960			1958-1949		
Belt - Fan; Ser. No. 351 & Before .....	229559	②▲9455HD	Belt - Fan .....	229559	▲9455HD
Belt - Fan; Ser. No. 352 & After .....	227470	▲9480HD			
Belt - P.S. ....	826215	▲9425HD			
Hose - Upper; Early .....		●25473			
Hose - Lower; Early .....		24224			
<b>707; 707XTB</b>			<b>CASE IH</b>		
<b>West Allis 4-Cyl. 226</b>			<b>1822</b>		
1969-1966			<b>Case 6TA590 Diesel</b>		
Belt - Hyd. Pump .....	548872	▲9455HD	1991-1986		
			Belt - A.C. ....	1250587C1	▲9415HD
			Belt - Fan & Alt. ....	J911565	▲K080580HD
			Hose - Lower - Pipe To Rad. ....		24436
<b>760XTB</b>			<b>1844</b>		
<b>Chevrolet 6-Cyl. 250</b>			<b>Case 6-Cyl. 505 Diesel</b>		
1970			1991-1986		
Belt - Alt./Gen. ....	1146660	7400	Belt - A.C. ....	1250587C1	▲9415HD
Belt - Gov. ....	1146702	7480	Belt - Fan & Alt. ....	J911565	▲K080580HD
Belt - Hyd. Pump .....	562203	▲9440HD			
<b>801; 802</b>			<b>2055</b>		
<b>Allis-Chalmers 6-Cyl. 262</b>			<b>Case 6-Cyl. 505 Diesel</b>		
1969-1966			1994-1990		
Belt - Fan; Ser. No. 68068 & Before .....	229211	▲9463HD	Belt - Fan To A.C. ....	0131403C1	▲9385HD
Belt - Fan; Ser. No. 68069 & After .....	237048	▲9455HD	Hose - Upper - Eng. To Pipe .....		☞21194
Belt - P.S. ....	826215	▲9425HD	Hose - Upper - Pipe To Rad. ....		24240
Hose - Upper .....		24228	Hose - Lower - Eng. To Pipe .....		21901
Hose - Lower .....		☞20957	Hose - Lower - Pipe To Rad. ....		24432
			<b>HESSTON</b>		
			<b>SP55</b>		
			<b>Ford 6-Cyl. 240</b>		
			1970		
			Belt - Fan .....		▲9405HD

②Two Required ☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>HESSTON - Continued</b>		
<b>SP55 – Continued</b>		
<b>Ford 6-Cyl. 240 – Continued</b>		
<b>1970 – Continued</b>		
Belt - Gov. ....		7250
Belt - W.P. & Alt. ....		7410
Hose - Upper .....		●26502
Hose - Lower .....		●26502
<b>INTERNATIONAL HARVESTER</b>		
<b>95</b>		
<b>IH D310 Diesel</b>		
<b>1974</b>		
Belt - Fan & Alt. ....	396543R1	②▲9640HD
Hose - Upper .....		●26510
Hose - Lower - Eng. To Pipe .....		24228
Hose - Lower - Pipe To Rad. ....		24228
<b>214 McCormick</b>		
<b>IH BD240</b>		
<b>1961-1958</b>		
Belt - Fan & Gen. ....	274705R1	TR28445
Hose - Upper .....		☞20611
		or ●26507
<b>1957-1956</b>		
Belt - Fan & Gen. ....	274705R1	TR24438
Hose - Upper .....		☞20611
		or ●26507
<b>IH D282 Diesel</b>		
<b>1961-1956</b>		
Belt - Fan & Gen. ....	312515R1	▲9525HD
Hose - Upper .....		☞20611
<b>214A McCormick</b>		
<b>IH BD240</b>		
<b>1961-1960</b>		
Belt - Fan & Gen. ....	274705R1	TR28445
Hose - Upper .....		☞20611
		or ●26507
<b>1959</b>		
Belt - Fan & Gen. ....	274705R1	TR24438
Hose - Upper .....		☞20611
		or ●26507
<b>1958</b>		
Belt - Fan & Gen. ....	274705R1	TR28445
Hose - Upper .....		☞20611
		or ●26507
<b>1957-1956</b>		
Belt - Fan & Gen. ....	274705R1	TR24438
Hose - Upper .....		☞20611
		or ●26507
<b>IH D282 Diesel</b>		
<b>1961-1956</b>		
Belt - Fan & Gen. ....	312515R1	▲9525HD
Hose - Upper .....		☞20611
<b>220 McCormick</b>		
<b>IH BD240</b>		
<b>1961</b>		
Belt - Fan & Gen. ....	274705R1	TR28445
Hose - Upper .....		☞20611
		or ●26507
<b>1960</b>		
Belt - Fan & Gen. ....	274705R1	TR24438
Hose - Upper .....		☞20611
		or ●26507
<b>1959-1958</b>		
Belt - Fan & Gen. ....	274705R1	TR28445
Hose - Upper .....		☞20611
		or ●26507
<b>1957-1956</b>		
Belt - Fan & Gen. ....	274705R1	TR24438

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>220 McCormick – Continued</b>		
<b>IH BD240 – Continued</b>		
<b>1957-1956 – Continued</b>		
Hose - Upper .....		☞20611
		or ●26507
<b>IH D282 Diesel</b>		
<b>1961-1956</b>		
Belt - Fan & Gen. ....	312515R1	▲9525HD
Hose - Upper .....		☞20611
<b>220A McCormick</b>		
<b>IH BD240</b>		
<b>1961-1959</b>		
Belt - Fan & Gen. ....	274705R1	TR28445
Hose - Upper .....		☞20611
		or ●26507
<b>1958-1956</b>		
Belt - Fan & Gen. ....	274705R1	TR24438
Hose - Upper .....		☞20611
		or ●26507
<b>IH D282 Diesel</b>		
<b>1961-1956</b>		
Belt - Fan & Gen. ....	312515R1	▲9525HD
Hose - Upper .....		☞20611
<b>414</b>		
<b>IH BD264 Diesel</b>		
<b>1962</b>		
Belt - Fan & Gen. ....	274705R1	TR28445
Hose - Upper .....		☞20611
<b>IH C263</b>		
<b>1962</b>		
Belt - Fan & Gen.; Ser. No. CH812E & Before .....	312515R1	▲9525HD
Belt - Fan & Gen.; Ser. No. CH813E & After ..	170780R1	▲9470HD
Hose - Upper .....		☞20611
<b>IH D282 Diesel</b>		
<b>1962</b>		
Belt - Fan & Gen.; Ser. No. CH812E & Before .....	312515R1	▲9525HD
Belt - Fan & Gen.; Ser. No. CH813E & After ..	379966R1	▲9540HD
Hose - Upper .....		☞20611
<b>416</b>		
<b>IH C263</b>		
<b>1965</b>		
Belt - Fan & Gen. ....	403617R1	▲9470HD
<b>IH D282 Diesel</b>		
<b>1965</b>		
Belt - Fan & Gen. ....	379966R1	▲9540HD
<b>420</b>		
<b>IH BD264 Diesel</b>		
<b>1962</b>		
Belt - Fan & Gen. ....	274705R1	TR28445
Hose - Upper .....		☞20611
<b>IH C263</b>		
<b>1962</b>		
Belt - Fan & Gen.; Ser. No. CH1371F & Before .....	312515R1	▲9525HD
Belt - Fan & Gen.; Ser. No. CH1372F & After ..	170780R1	▲9470HD
Hose - Upper .....		☞20611
<b>IH D282 Diesel</b>		
<b>1962</b>		
Belt - Fan & Gen.; Ser. No. CH1371E & Before .....	312515R1	▲9525HD
Belt - Fan & Gen.; Ser. No. CH1372F & After ..	379966R1	▲9540HD
Hose - Upper .....		☞20611

②Two Required ☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>422</b>		
<b>IH C263</b>		
1965		
Belt - Fan & Gen. ....	403617R1	▲9470HD
<b>IH D282 Diesel</b>		
1965		
Belt - Fan & Gen. ....	379966R1	▲9540HD
<b>616; 622</b>		
<b>IH C291</b>		
1968-1967		
Belt - W.P. & Alt. ....	397175R1	▲9476HD
Hose - By Pass .....		20338
<b>IH D310 Diesel</b>		
1968-1967		
Belt - W.P. & Alt. ....	395539R1	▲9630HD
<b>782</b>		
<b>IH D358 Diesel</b>		
1978		
Belt - Fan & Alt. ....	130725C1	②▲9700HD
<b>JOHN DEERE</b>		
<b>99</b>		
<b>John Deere 248</b>		
1973-1968		
Belt - Fan & Gen. ....	T626T	7480
Belt - P.S. ....		7375
<b>John Deere NA217G</b>		
1973-1968		
Belt - Fan & Gen. ....	T626T	7480
Belt - P.S. ....		7375
<b>John Deere NA248D Diesel</b>		
1973-1968		
Belt - Fan & Gen. ....	T19396	7460
Belt - P.S. ....		7375
<b>John Deere NB217G</b>		
1973-1968		
Belt - Fan & Gen. ....	T626T	7480
Belt - P.S. ....		7375
<b>299</b>		
<b>John Deere NA248D Diesel</b>		
1961		
Belt - Fan & Gen. ....	T19396	7460
Belt - P.S. ....		7375
<b>John Deere NB217G</b>		
1961		
Belt - Fan & Gen. ....	T626T	7480
Belt - P.S. ....		7375
<b>482</b>		
<b>John Deere 219</b>		
1973-1968		
Belt - Fan & Alt. ....	AT23317	7575
<b>John Deere 329</b>		
1973-1968		
Belt - Fan & Alt. ....	AT23317	7575
<b>484</b>		
<b>John Deere 6-Cyl. 329 Diesel</b>		
1973-1968		
Belt - Fan & Alt.; Ser. No. 276 & Before .....	AT23317	7575
Belt - Fan & Alt.; Ser. No. 277 & After .....	AN190205	7585

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>484 - Continued</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
<b>1973-1971</b>		
Belt - Boll Box Drive .....	M40757	6877
Belt - Fan & Alt.; Ser. No. 276 & Before .....	AT23317	7575
Belt - Fan & Alt.; Ser. No. 277 & After .....	AN190205	7585
Belt - Hyd. Pump .....	N117398	B46
Belt - Row Unit Drive; W/30" Offset Cross Auger; W/119" Belt O.C. ....	N12551	C115
Belt - Row Unit Drive; W/30" Offset Cross Auger; W/64" Belt O.C. ....	N15201	C60
Belt - Row Unit Drive; W/O 30" Offset Cross Auger; W/111" Belt O.C. ....	E58483	C107
Belt - Row Unit Drive; W/O 30" Offset Cross Auger; W/126" Belt O.C. ....	H136963	C122
Belt - Row Unit Drive For Extension; W/102" Belt O.C. ....	N121114	C98
Belt - Row Unit Drive For Extension; W/111" Belt O.C. ....	E58483	C107
Belt - Row Unit Drive For Extension; W/119" Belt O.C. ....	N12551	C115
Belt - Row Unit Drive For Extension; W/83" Belt O.C. ....	L4490N	C79
Belt - Rubber Cushion Eng. Mountings; W/48" Belt O.C. ....	N115368	B45
Belt - Rubber Cushion Eng. Mountings; W/49" Belt O.C. ....	N117398	B46
<b>1970</b>		
Belt - Boll Box Drive .....	M40757	A75
Belt - Fan & Alt.; Ser. No. 276 & Before .....	AT23317	7575
Belt - Fan & Alt.; Ser. No. 277 & After .....	AN190205	7585
Belt - Hyd. Pump .....	N117398	B46
Belt - Row Unit Drive; W/30" Offset Cross Auger; W/119" Belt O.C. ....	N12551	C115
Belt - Row Unit Drive; W/30" Offset Cross Auger; W/64" Belt O.C. ....	N15201	C60
Belt - Row Unit Drive; W/O 30" Offset Cross Auger; W/111" Belt O.C. ....	E58483	C107
Belt - Row Unit Drive; W/O 30" Offset Cross Auger; W/126" Belt O.C. ....	H136963	C122
Belt - Row Unit Drive For Extension; W/102" Belt O.C. ....	N121114	C98
Belt - Row Unit Drive For Extension; W/111" Belt O.C. ....	E58483	C107
Belt - Row Unit Drive For Extension; W/119" Belt O.C. ....	N12551	C115
Belt - Row Unit Drive For Extension; W/83" Belt O.C. ....	L4490N	C79
Belt - Rubber Cushion Eng. Mountings; W/48" Belt O.C. ....	N115368	B45
Belt - Rubber Cushion Eng. Mountings; W/49" Belt O.C. ....	N117398	B46
<b>1969-1968</b>		
Belt - Boll Box Drive .....	M40757	6877
Belt - Fan & Alt.; Ser. No. 276 & Before .....	AT23317	7575
Belt - Fan & Alt.; Ser. No. 277 & After .....	AN190205	7585
Belt - Hyd. Pump .....	N117398	B46
Belt - Row Unit Drive; W/30" Offset Cross Auger; W/119" Belt O.C. ....	N12551	C115
Belt - Row Unit Drive; W/30" Offset Cross Auger; W/64" Belt O.C. ....	N15201	C60
Belt - Row Unit Drive; W/O 30" Offset Cross Auger; W/111" Belt O.C. ....	E58483	C107
Belt - Row Unit Drive; W/O 30" Offset Cross Auger; W/126" Belt O.C. ....	H136963	C122
Belt - Row Unit Drive For Extension; W/102" Belt O.C. ....	N121114	C98
Belt - Row Unit Drive For Extension; W/111" Belt O.C. ....	E58483	C107
Belt - Row Unit Drive For Extension; W/119" Belt O.C. ....	N12551	C115
Belt - Row Unit Drive For Extension; W/83" Belt O.C. ....	L4490N	C79
Belt - Rubber Cushion Eng. Mountings; W/48" Belt O.C. ....	N115368	B45
Belt - Rubber Cushion Eng. Mountings; W/49" Belt O.C. ....	N117398	B46

②Two Required ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>499</b>		
<b>John Deere 217</b>		
1973-1968		
Belt - A.C. ....	N113642	▲9440HD
Belt - Fan & Alt.; W/48 1/8" Belt O.C. ....	T626T	7480
Belt - Fan & Alt.; W/57 5/8" Belt O.C. ....	AT23317	7575
<b>John Deere 219</b>		
1973-1968		
Belt - A.C. ....	N113642	▲9440HD
Belt - Fan & Alt.; W/48 1/8" Belt O.C. ....	T626T	7480
Belt - Fan & Alt.; W/57 5/8" Belt O.C. ....	AT23317	7575
<b>John Deere 329</b>		
1973-1968		
Belt - A.C. ....	N113642	▲9440HD
Belt - Fan & Alt.; W/48 1/8" Belt O.C. ....	T626T	7480
Belt - Fan & Alt.; W/57 5/8" Belt O.C. ....	AT23317	7575
<b>699</b>		
<b>John Deere 303</b>		
1973-1968		
Belt - A.C. ....	N113642	▲9440HD
Belt - Fan & Alt.; W/48 1/8" Belt O.C. ....	T626T	7480
Belt - Fan & Alt.; W/57 5/8" Belt O.C. ....	AT23317	7575
<b>John Deere 329</b>		
1973-1968		
Belt - A.C. ....	N113642	▲9440HD
Belt - Fan & Alt.; W/48 1/8" Belt O.C. ....	T626T	7480
Belt - Fan & Alt.; W/57 5/8" Belt O.C. ....	AT23317	7575
<b>7440</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1985-1983		
Belt - Auger; W/107" Belt O.C. ....	N121113	C103
Belt - Auger; W/110" Belt O.C. ....	N125041	C106
Belt - Auger; W/111" Belt O.C. ....	E58483	C107
Belt - Auger; W/91" Belt O.C. ....	N31437	C87
Belt - Auger; W/97" Belt O.C. ....	L4339N	C93
Belt - Condenser ....	N117674	▲9463HD
Belt - Fan ....	N129368	B74
Belt - Fan To Alt. ....	AN273251	②7590
Belt - Hyd. Pump ....	N220403	B50
<b>9900</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1977-1974		
Belt - A.C.; W/Delco A.C. Compr. ....	N117674	▲9463HD
Belt - A.C.; W/York A.C. Compr. ....	N113642	▲9440HD
Belt - W.P. & Alt. ....	AT23317	②7575
<b>9910</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1982-1978		
Belt - A.C. ....	N117674	▲9463HD
Belt - W.P. & Alt. ....	AN190205	7585
<b>9920</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1987-1983		
Belt - A.C. ....	N117674	▲9463HD
Belt - W.P. & Alt. ....	AN190205	7585
<b>9940</b>		
<b>John Deere 6-Cyl. 7.6 L Diesel</b>		
1985-1980		
Belt - A.C. ....	R71602	▲9425HD
Belt - Fan ....	AR86496	②▲9670HD
<b>9950</b>		
<b>John Deere 6-Cyl. 7.6 L Diesel</b>		
1990-1986		
Belt - A.C. ....	R73189	▲9430HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9950 - Continued</b>		
<b>John Deere 6-Cyl. 7.6 L Diesel - Continued</b>		
1990-1986 - Continued		
Belt - Fan & Alt. ....	AR74662	②▲9660HD
<b>9960</b>		
<b>John Deere 6-Cyl. 7.6 L Diesel</b>		
1992-1989		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt. ....	RE41942	②▲9660HD
<b>9965</b>		
<b>John Deere 6-Cyl. 7.6 L Diesel</b>		
1997-1993		
Belt - Fan & Alt. ....	RE41942	②▲9660HD

②Two Required ▲Standard Belt May Also Be Available



Manufacturers' Part Number Shown for Reference Only

Application	OEM No.	Our No.
<b>ALLIS-CHALMERS</b>		
<b>60 All-Crop</b>		
<b>Allis-Chalmers B125</b>		
1953-1935		
Belt - Fan .....	207003	TR22322
Belt - Fan & Gen. ....	209656	TR22363
<b>FARMHAND</b>		
<b>F600</b>		
<b>Detroit Diesel 6-71 Diesel</b>		
1991		
Belt - A.C.; W/Turbo .....	1A60664	②▲9520HD
Belt - Alt.; W/Turbo .....	1A60664	②▲9520HD
Belt - Fan; W/Turbo .....	5137906	③▲9630HD
<b>FIELD QUEEN</b>		
<b>1412</b>		
<b>Caterpillar 3208 Diesel</b>		
1975-1973		
Belt - A.C. ....		▲9570HD
Belt - Alt. ....		②▲9510HD
Belt - Fan ....		②▲9525HD
Hose - Upper - Eng. To Pipe .....		●26512
Hose - Upper - Pipe To Rad. ....		24448
Hose - Lower - Eng. To Pipe .....		24444
Hose - Lower - Pipe To Rad. ....		●26537
<b>FQ</b>		
<b>Caterpillar 3208 Diesel</b>		
1975-1973		
Belt - A.C. ....		▲9580HD
Belt - Fan .....	9L894	②▲9520HD
Belt - W.P. & Alt. ....		②▲9510HD
Hose - Upper - Eng. To Pipe .....		●26512
Hose - Upper - Pipe To Rad. ....		24440
Hose - Lower - Eng. To Pipe .....		24436
<b>FQS</b>		
<b>Caterpillar 3208 Diesel</b>		
1975-1973		
Belt - A.C. ....		▲9580HD
Belt - Fan .....	9L894	②▲9520HD
Belt - W.P. & Alt. ....		②▲9510HD
Hose - Upper .....		●26512
<b>FQSD</b>		
<b>Detroit Diesel 6-71 Diesel</b>		
1975-1973		
Belt - Alt. ....		②▲9400HD
Belt - Fan .....		③▲9620HD
Hose - Upper - Eng. To Pipe (Left) .....		●26530
Hose - Upper - Eng. To Pipe (Right) .....		③<20206
		or ●26530
Hose - Upper - Pipe To Rad. ....		24444
Hose - Lower - Eng. To Pipe .....		24442
<b>FOX RIVER</b>		
<b>FA</b>		
<b>Detroit Diesel 4-53 Diesel</b>		
1968-1959		
Belt - Fan .....		②TR22443
Belt - Gen. ....	3224367	TR28390
Hose - Upper .....		20046
		or ●26602
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232

Application	OEM No.	Our No.
<b>FOX RIVER - Continued</b>		
<b>Max I</b>		
<b>Detroit Diesel 6V-53 Diesel</b>		
1973-1972		
Belt - Fan .....		③▲9510HD
Belt - Gen. ....		▲9365HD
Belt - Hyd. Pump .....		TR22508
Hose - Upper - Right Side .....		●26517
Hose - Lower .....		●26536
<b>Max II</b>		
<b>Detroit Diesel 6V-71 Diesel</b>		
1976-1973		
Belt - Alt./Gen. ....		▲9360HD
Belt - Fan .....		③▲9520HD
Belt - Hyd. Pump .....		TR22508
Hose - Upper - Left Side .....		●26516
Hose - Upper - Right Side .....		●26517
Hose - Lower .....		●26536
<b>Super D</b>		
<b>Detroit Diesel 4-53 Diesel</b>		
1973-1972		
Belt - Fan .....		▲9420HD
Belt - Gen. ....		▲9375HD
Belt - Hyd. Pump .....		▲9625HD
Hose - Upper .....		●26502
Hose - Lower .....		●26504
<b>GEHL</b>		
<b>Chop King</b>		
<b>Waukesha 135GZ</b>		
1966-1965		
Belt - Alt. ....		▲9435HD
Belt - Fan .....		②▲9480HD
Hose - Upper .....		③<20611
		or ●26510
Hose - Lower .....		24240
<b>INTERNATIONAL HARVESTER</b>		
<b>20C</b>		
<b>IH BD240</b>		
1937-1930		
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>IH C263</b>		
1937-1930		
Hose - By Pass .....		20338
<b>IH SD240</b>		
1937-1930		
Belt - Fan & Gen.; W/46 5/8" Belt O.C. ....		TR24461
Belt - Fan & Gen.; W/47 3/4" Belt O.C. ....		TR28483
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>36</b>		
<b>IH BD240</b>		
1957		
Belt - Fan & Gen. ....	274705R1	TR24438
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>IH C263</b>		
1957		
Hose - By Pass .....		20338
<b>IH SD240</b>		
1957		
Belt - Fan & Gen.; W/46 5/8" Belt O.C. ....		TR24461
Belt - Fan & Gen.; W/47 3/4" Belt O.C. ....		TR28483

②Two Required ③Three Required ③<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>36 - Continued</b>		
<b>IH SD240 - Continued</b>		
1957 - Continued		
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>50</b>		
<b>IH C263</b>		
1950		
Belt - Fan .....	170481R1	▲9463HD
<b>JOHN DEERE</b>		
<b>5460</b>		
<b>John Deere 6-Cyl. 619 Diesel</b>		
1981-1977		
Belt - A.C. ....	R46098	▲9415HD
Belt - Fan & Alt. ....	AR86496	②▲9670HD
<b>5820</b>		
<b>John Deere 6-Cyl. 619 Diesel</b>		
1986-1982		
Belt - A.C. ....		9300
Belt - Fan & Alt. ....		②▲9710HD
<b>5830</b>		
<b>John Deere 6-Cyl. 619 Diesel</b>		
1994-1986		
Belt - Air Compr. ....	T55320	▲9405HD
Belt - Fan & Alt. ....	AR87671	②▲9700HD
Belt - Hyd. Pump .....	E72830	▲9660HD
<b>6750</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2005-2004		
Belt - Alt. ....	R503505	▲K080855HD
Belt - Fan .....	R502461	▲K120702HD
Hose - Lower - Eng. To Pipe .....	R57396	21400
<b>6850</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2002-1998		
Belt - Alt. ....	R503505	▲K080855HD
Belt - Fan .....	R502461	▲K120702HD
<b>6910 Harvester</b>		
<b>Cummins 6-Cyl. 14.0 L Diesel</b>		
1994-1993		
Belt - Alt.; W/45 3/4" Belt O.C. ....		▲9455HD
Belt - Alt.; W/47 3/4" Belt O.C. ....		▲9470HD
Belt - Fan & Idler .....		TR28501
Belt - W.P. ....	217638	▲K060435HD
Hose - Upper - Eng. To Pipe .....		②<22177
Hose - Upper - Pipe To Rad. ....		24240
Hose - Lower - Eng. To Pipe .....		24440
Hose - Lower - Pipe To Rad. ....		20564
Hose - By Pass .....		24224
<b>6950</b>		
<b>Cummins N14 Diesel</b>		
2005-2004		
Belt - W.P. ....		▲K060425HD
<b>7200 Harvester</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2007-2004		
Belt - Fan & Alt.; W/150A. Alt. ....	L114293	▲K080994HD
<b>7250</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2008		
Belt - Serpentine .....	L114293	▲K080994HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>7300</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2007-2004		
Belt - Alt.; W/150A. Alt. ....	L115660	▲K080839HD
Belt - Fan .....	R503312	▲K120720HD
Hose - Lower - Eng. To Pipe .....	R57396	21400
<b>7350</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>		
2008		
Belt - Alt. ....	L115660	▲K080839HD
Belt - Fan - From C.S. ....	R503312	▲K120720HD
<b>7400 Harvester</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2007-2004		
Belt - Fan .....	R502461	▲K120702HD
Hose - Lower - Eng. To Pipe .....	R57396	21400
<b>7450 Harvester</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>		
2008		
Belt - Fan - From C.S. ....	R502461	▲K120702HD
<b>7500 Harvester</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2007-2004		
Belt - Fan .....	R502461	▲K120702HD
Hose - Lower - Eng. To Pipe .....	R57396	21400
<b>7550</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>		
2008		
Belt - Fan - From C.S. ....	R502461	▲K120702HD
<b>7700 Harvester</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2007-2004		
Belt - Fan .....	R502461	▲K120702HD
Tensioner Assy. ....	RE506352	38591
Hose - Lower - Eng. To Pipe .....	R57396	21400
<b>7800 Harvester</b>		
<b>Cummins 6-Cyl. 915 Diesel</b>		
2007-2004		
Belt - Alt. ....	L110599	▲K060660HD
Belt - Fan .....	Z101214	▲K120911HD
<b>NEW HOLLAND</b>		
<b>818</b>		
<b>Chevrolet V-8 348</b>		
1960		
Belt - Fan & Gen. ....	3767013	7585
Belt - Fan & Hyd. Pump .....		7541
Belt - Gov. ....		▲9505HD
Hose - Upper .....		●25476
Hose - Lower .....		●26511
<b>1818</b>		
<b>Caterpillar 3150 Diesel</b>		
1979		
Hose - Upper .....		●26512
Hose - Lower .....		●26512
<b>Caterpillar 3160 Diesel</b>		
1979		
Hose - Upper .....		●26512
Hose - Lower .....		●26517

②Two Required <Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>1818 - Continued</b>		
<b>Ford V-8 391</b>		
1979		
Hose - Upper .....		②<21379
		or ●26511
Hose - Lower .....		●25482
<b>1880</b>		
<b>Caterpillar 3150 Diesel</b>		
1975-1968		
Belt - Fan & Alt. ....		②▲9510HD
Belt - Hyd. Pump .....	191444	▲9550HD
<b>Caterpillar 3160 Diesel</b>		
1975-1968		
Belt - Fan & Alt. ....		②▲9510HD
Belt - Hyd. Pump .....	191444	▲9550HD
<b>Caterpillar 3208 Diesel</b>		
1975-1968		
Belt - Fan & Alt. ....	254804	②▲9510HD
Belt - Hyd. Pump .....	280332	7560
Hose - Upper .....		●26512
Hose - Lower .....		●26512
<b>Ford V-8 391</b>		
1975-1968		
Belt - Fan & Alt. ....	C5TE 8620 H	▲9470HD
Belt - Gov. ....		7490
Belt - Hyd. Pump .....		7470
<b>1890</b>		
<b>Caterpillar 3208 Diesel</b>		
1978-1976		
Belt - Fan & Alt. ....	254804	②▲9510HD
Hose - Upper .....		●26512
Hose - Lower .....		●26524
<b>1900</b>		
<b>Caterpillar 3406 Diesel</b>		
1989-1982		
Belt - Alt. ....	616163	▲9480HD
<b>1915</b>		
<b>Caterpillar 3306 Diesel</b>		
1994-1987		
Belt - Alt. ....		▲9500HD
Belt - Fan & A.C. ....		9775
<b>2100</b>		
<b>Caterpillar 3406 Diesel</b>		
1989-1980		
Hose - Upper - Eng. To Pipe .....		●26530
Hose - Upper - Pipe To Rad. ....		24240
Hose - Lower - Eng. To Pipe .....		24248
Hose - Lower - Pipe To Rad. ....		24248
<b>2115</b>		
<b>Caterpillar 3406 Diesel</b>		
1994-1987		
Hose - Lower - Eng. To Pipe .....		②<24948
Hose - Lower - Pipe To Rad. ....		②<24948
<b>OLIVER</b>		
<b>840</b>		
<b>Hercules 6-Cyl. 478 Diesel</b>		
1976-1970		
Belt - Fan & Alt. ....	524743E	②▲9590HD
Belt - P.S. ....		▲9570HD
Hose - Upper .....		●26511

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Manufacturers' Part Number Shown for Reference Only

Application	OEM No.	Our No.
<b>FREEMAN</b>		
<b>330T</b>		
<b>Cummins 4-Cyl. 3.9 L Diesel</b>		
1998-1968		
Belt - Fan & Alt. ....	3911560	▲K080550HD
Hose - Upper .....		≠21379
Hose - Lower - Eng. To Pipe .....		≠20847
Hose - Lower - Pipe To Rad. ....		≠21307
<b>370</b>		
<b>Deutz F4L912 Diesel</b>		
2005-1986		
Belt - Alt. ....		7435
Belt - Blower .....		7512
<b>370SP</b>		
<b>Cummins 4-Cyl. 3.9 L Diesel</b>		
2004-1986		
Belt - Fan & Alt. ....	3911560	▲K080550HD
Belt - V.P. ....		▲9463HD
Hose - Upper - Eng. To Pipe .....		≠21379
		or ●26509
Hose - Upper - Pipe To Rad. ....		24432
Hose - Lower - Eng. To Pipe .....		≠20206
Hose - Lower - Pipe To Rad. ....		24432
<b>4400</b>		
<b>Cummins 6-Cyl. 5.9 L Diesel</b>		
Belt - A.C. ....		▲9600HD
Belt - Fan & Alt.; W/55 5/8" Belt O.C. ....	3911560	▲K080550HD
Belt - Fan & Alt.; W/56 5/8" Belt O.C. ....	3911588	▲K080560HD
Belt - V.P. ....		▲9463HD
Hose - Upper .....		●26505
Hose - Lower - Eng. To Pipe .....		21307
Hose - Lower - Pipe To Rad. ....		≠20206
<b>5000</b>		
<b>Cummins 6-Cyl. 5.9 L Diesel</b>		
1991-1990		
Belt - A.C. ....		▲9600HD
Belt - Fan & Alt.; W/55 5/8" Belt O.C. ....	3911560	▲K080550HD
Belt - Fan & Alt.; W/56 5/8" Belt O.C. ....	3911588	▲K080560HD
Belt - V.P. ....		▲9463HD
Hose - Upper .....		●26505
Hose - Lower - Eng. To Pipe .....		21307
Hose - Lower - Pipe To Rad. ....		≠20206
<b>6000</b>		
<b>Cummins 6-Cyl. 5.9 L Diesel</b>		
Belt - A.C. ....		▲9600HD
Belt - Fan & Alt.; W/55 5/8" Belt O.C. ....	3911560	▲K080550HD
Belt - Fan & Alt.; W/56 5/8" Belt O.C. ....	3911588	▲K080560HD
Belt - V.P. ....		▲9463HD
Hose - Upper .....		●26505
Hose - Lower .....		●26515
<b>GEHL</b>		
<b>2650</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1988-1987		
Belt - A.C. ....	02032194	▲9465HD
Belt - Fan & Alt. ....	02032158	▲9520HD
Hose - Upper .....		●25478
<b>INTERNATIONAL HARVESTER</b>		
<b>50T McCormick-Deering; 50W McCormick-Deering</b>		
<b>IH C60</b>		
1952-1944		
Belt - Fan .....	368082R1	TR24315
Belt - Gen. ....	351321R1	6821
Hose - Upper .....		24232
Hose - Lower - Eng. To Pipe .....		24232

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>50T McCormick-Deering; 50W McCormick-Deering - Continued</b>		
<b>IH C60 - Continued</b>		
1952-1944 - Continued		
Hose - Lower - Pipe To Rad. ....		24226
<b>55T McCormick-Deering; 55W McCormick-Deering</b>		
<b>IH C60</b>		
1959-1953		
Belt - Fan .....	368082R1	TR24315
Belt - Gen. ....	351321R1	6821
Hose - Upper .....		24232
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24226
<b>IH C113</b>		
1959-1953		
Belt - Fan .....	271667R1	TR24315
Belt - Fan & W.P. ....		TR28346
Belt - Gen. ....	49291D	9260
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>IH C123</b>		
1959-1953		
Belt - Fan; W/31 3/4" Belt O.C. ....	271667R1	TR24315
Belt - Fan; W/35 1/2" Belt O.C. ....	368084R1	TR26353
Belt - Fan & W.P. ....		TR28346
Belt - Gen. ....	49291D	9260
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>56T; 56W</b>		
<b>IH C123</b>		
1959-1953		
Belt - Fan .....		TR28346
Belt - Fan & W.P. ....	368084R1	TR26353
Belt - Gen. ....	49291D	9260
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>57T; 57W</b>		
<b>IH C123</b>		
1973-1972		
Belt - Fan .....		TR28346
Belt - Fan & W.P. ....	368084R1	TR26353
Belt - Gen. ....	49291D	9260
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>NEW HOLLAND</b>		
<b>505T; 505W</b>		
<b>Deutz F3L912 Diesel</b>		
1991-1984		
Belt - Alt. ....	259347	7417
<b>1047</b>		
<b>Ford 6-Cyl. 240</b>		
1972-1965		
Belt - Fan .....		3VX900
Belt - Gov. ....		▲9290HD
Belt - W.P. & Alt. ....		▲9420HD
Hose - Upper - Eng. To Pipe .....		●25476
Hose - Upper - Pipe To Rad. ....		24224
Hose - Lower - Eng. To Pipe .....		●26611
Hose - Lower - Pipe To Rad. ....		24228
<b>1048</b>		
<b>Ford V-8 361</b>		
1976		
Belt - J.S. ....	519145	7420

≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>1048 - Continued</b>		
<b>Ford V-8 361 - Continued</b>		
<b>1976 - Continued</b>		
Belt - W.P. & Alt. ....		▲9463HD
Hose - Upper - Eng. To Pipe .....		●26504
Hose - Upper - Pipe To Rad. ....		≡<20957
Hose - Lower - Eng. To Pipe .....		●26504
Hose - Lower - Pipe To Rad. ....		●26501
<b>1049</b>		
<b>Ford V-8 361</b>		
<b>1976-1970</b>		
Belt - Fan .....		7335
Belt - Fan & Alt. ....	C5TE 8620 A	②▲9463HD
Belt - Idler .....		7425
Hose - Upper - Eng. To Pipe .....		●26504
Hose - Upper - Pipe To Rad. ....		≡<20957
	or	●26603
Hose - Lower - Eng. To Pipe .....		●26504
Hose - Lower - Pipe To Rad. ....		●26501
Hose - By Pass .....		28441
<b>1049 Super</b>		
<b>Ford V-8 361</b>		
<b>1976</b>		
Belt - Fan .....	525351	7355
Belt - J.S. ....	519145	7420
Belt - W.P. & Alt. ....		②7440
<b>1283T; 1283W</b>		
<b>Ford 6-Cyl. 240</b>		
<b>1980-1974</b>		
Belt - Fan .....	C7JZ 8620 H	▲9405HD
Belt - Hyd. Pump .....	133929	▲9430HD
Belt - W.P. & Alt. ....	384205	▲9425HD
Belt - W.P. & Gov. ....		▲9455HD
Hose - Upper .....		●26502
Hose - Lower .....		●26504

Agricultural Equipment

②Two Required ≡<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Manufacturers' Part Number Shown for Reference Only

Application	OEM No.	Our No.
<b>AG-CHEM EQUIPMENT</b>		
<b>804 Ag-Gator</b>		
<b>Ford V-8 330</b>		
1980		
Belt - Fan .....		②▲9570HD
Belt - Gov. ....		7560
<b>1253 Terra-Gator</b>		
<b>Cummins V555 Diesel</b>		
1979-1973		
Belt - Alt. ....	178398	②7340
Belt - Fan .....	204481	③▲9625HD
Belt - Hyd. Pump .....		②▲9580HD
Hose - Upper .....		●26513
Hose - Lower .....		●26519
<b>2004 Ag-Gator</b>		
<b>Cummins V378 Diesel</b>		
1983-1980		
Belt - Fan & W.P. ....	178686	②TR22344
Belt - Pump .....		②▲9580HD
Hose - Lower .....		●26519
<b>Cummins V504 Diesel</b>		
1983-1980		
Belt - A.C. ....		7410
Belt - Fan & W.P. ....		②TR22525
Belt - Fan To Alt. ....		②7370
Belt - Hyd. Pump .....		②▲9580HD
Hose - Upper .....		●26512
Hose - Lower .....		●26522
<b>BOBCAT-MELROE</b>		
<b>3430; 3630</b>		
<b>Peugeot 4-Cyl. Diesel</b>		
1997-1994		
Belt - A.C. & A.P. ....		K050545
Belt - Fan & Alt. ....	6660942	▲9525HD
Belt - W.P. ....	6660943	▲9385HD
<b>CASE IH</b>		
<b>3230</b>		
<b>Case 4-Cyl. 206 Diesel</b>		
1997-1994		
Belt - A.C. ....	84657C1	▲9670HD
<b>SPX4410</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2006-2004		
Belt - A.C. ....	A184652	▲9400HD
Belt - Fan & Alt. ....	3929003	▲K080774HD
<b>FMC</b>		
<b>393CPD</b>		
<b>John Deere 4039D Diesel</b>		
Belt - Fan & Alt. ....	T23526	TR24500
Belt - P.T.O. ....		3VX530
Belt - Pulley To Drive .....		3VX530
Hose - Upper .....		24224
Hose - Lower .....		24432
<b>HAHN</b>		
<b>880</b>		
<b>Perkins 4-Cyl. Diesel</b>		
Belt - C.S. To Pump .....		A46
Belt - Fan & Alt. ....	27923	▲9510HD
Hose - Upper .....		23520

Application	OEM No.	Our No.
<b>HAHN - Continued</b>		
<b>H670; H770</b>		
<b>Ford 4-Cyl. 172</b>		
Belt - Fan - From J.S. ....		▲9380HD
Belt - J.S. ....		▲9555HD
Belt - W.P. & Alt. ....		▲9420HD
Hose - Upper - Eng. To Pipe .....		②●25255
Hose - Lower - Eng. To Pipe .....		②●25480
<b>Hi-Boy</b>		
<b>Ford 4-Cyl. 172</b>		
Belt - Fan - From J.S. ....	28278	▲9360HD
Belt - W.P. & Alt. ....		▲9420HD
Hose - Upper - Eng. To Pipe .....		●25480
Hose - Upper - Pipe To Rad. ....		●25480
Hose - Lower - Eng. To Pipe .....		●25255
Hose - Lower - Pipe To Rad. ....		●25255
<b>Ford 4-Cyl. 172 Diesel</b>		
Belt - Fan .....		▲9360HD
Belt - Hyd. Pump .....		7410
Belt - J.S. ....		▲9550HD
Belt - W.P. & Alt. ....		▲9420HD
<b>Super Go-Boy</b>		
<b>Ford 6-Cyl.</b>		
Belt - Fan .....		▲9395HD
Belt - Gov. ....		7260
Hose - Upper .....		●25532
Hose - Lower .....		20608
<b>INTERNATIONAL HARVESTER</b>		
<b>660 Sprayer; 770; 780</b>		
<b>IH 4-Cyl. 135</b>		
Belt - Fan & Gen.; Std. Models .....	403580R1	7430
Belt - Fan & Gen.; W/High Clearance Style ....	387920R1	7425
<b>IH 4-Cyl. 146</b>		
Belt - Fan & Gen.; Std. Models .....	403580R1	7430
Belt - Fan & Gen.; W/High Clearance Style ....	387920R1	7425
<b>IH 4-Cyl. 153</b>		
Belt - Fan & Gen.; Std. Models .....	403580R1	7430
Belt - Fan & Gen.; W/High Clearance Style ....	387920R1	7425
<b>JOHN DEERE</b>		
<b>600 Sprayer</b>		
<b>John Deere 3-Cyl. 152 Diesel</b>		
Belt - Hyd. Pump; Ser. No. 1600 & Before .....		7312
Belt - Hyd. Pump; Ser. No. 1601 Thru 3699 ...	N150023	7330
Belt - Hyd. Pump; Ser. No. 3700 & After .....	N150864	TR22545
Belt - W.P.; Ser. No. 3699 & Before .....	T12042	7410
Belt - W.P.; Ser. No. 3700 & After .....	T20161	TR22495
<b>600A</b>		
<b>John Deere 3-Cyl. 152 Diesel</b>		
Belt - Fan & Alt. ....	T20161	TR22495
Belt - Hyd. Pump .....	N153364	TR22570
<b>700</b>		
<b>John Deere 3-Cyl. 152 Diesel</b>		
Belt - Hyd. Pump; Ser. No. 1099 & Before .....	N150023	7330
Belt - Hyd. Pump; Ser. No. 1100 & After .....	N150864	TR22545
Belt - W.P.; Ser. No. 1099 & Before .....	T12042	7410
Belt - W.P.; Ser. No. 1100 & After .....	T20161	TR22495
<b>734</b>		
<b>John Deere 3-Cyl. 152 Diesel</b>		
Belt - Hyd. Pump .....	N150864	TR22545
Belt - W.P. ....	T20161	TR22495
<b>6000</b>		
<b>John Deere 4-Cyl. 239 Diesel</b>		
1990-1979		
Belt - A.C.; W/61 3/8" Belt O.C. ....		▲9610HD

②Two Required ③Three Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6000 - Continued</b>		
<b>John Deere 4-Cyl. 239 Diesel - Continued</b>		
<b>1990-1979 - Continued</b>		
Belt - A.C.; W/63 7/8" Belt O.C. ....		◆9635HD
Belt - Fan & Alt. .... T20334		TR22474
Belt - P.S. .... N154412		TR22434
Hose - Upper .....		●25476
<b>WILMAR</b>		
<b>Air Ride</b>		
<b>John Deere 4-Cyl. Diesel</b>		
<b>1996-1991</b>		
Belt - A.C.; W/Turbo .....		◆9420HD
Hose - Upper; W/Turbo .....		●26510
Hose - Lower; W/Turbo .....		●26523

●Flexible Coolant Hose ◆Standard Belt May Also Be Available

Agricultural Equipment



Manufacturers' Part Number Shown for Reference Only

Application	OEM No.	Our No.	Application	OEM No.	Our No.
<b>AGCO</b>			<b>AGCO - Continued</b>		
<b>8360</b>			<b>RT95 – Continued</b>		
<b>Cummins N14 Diesel</b>			<b>Cummins 6-Cyl. 5.9 L Diesel – Continued</b>		
2001-1996			2003-2002 – Continued		
Belt - A.C. ....	72526174	▲9385HD	Tensioner Assy. - Alt. ....	3936206	38513
Belt - Fan ....	72526447	▲K060435HD	Tensioner Pulley - Alt. ....		36091
<b>8425</b>			<b>RT115</b>		
<b>Cummins N14 Diesel</b>			<b>Cummins 6-Cyl. 5.9 L Diesel</b>		
2001-1996			2004-2002		
Belt - A.C. ....	72526174	▲9385HD	Belt - Alt. ....	3925953	▲K080585HD
Belt - Fan ....	72526447	▲K060435HD	Tensioner Assy. - Alt. ....	3936206	38513
<b>Detroit Diesel 6-Cyl. 774 Diesel</b>			Tensioner Pulley - Alt. ....		36091
1997-1996			<b>RT135</b>		
Belt - Alt. ....	71369747	②▲9480HD	<b>Cummins 6-Cyl. 6.7 L Diesel</b>		
Belt - Fan ....	3633190M3	▲9490HD	2005-2004		
<b>9130; 9150</b>			Belt - Alt. ....	3967387	K080644
<b>Deutz 6-Cyl. 374 Diesel</b>			Belt - Fan ....	3966783	▲K080590HD
1993-1991			Tensioner Assy. - Fan ....	3937553	38504
Belt - A.C. ....	72163023	AX36	Tensioner Pulley - Fan ....		36091
Belt - Alt. ....	72161393	▲9480HD	<b>RT140A</b>		
Belt - Fan ....	2235177	②7550	<b>AGCO 6-Cyl. 402 Diesel</b>		
<b>9170; 9190</b>			2009		
<b>Deutz 6-Cyl. 584 Diesel</b>			Belt - Fan & Alt.; W/120A. Alt. ....	4273187M1	▲K080680HD
1993-1991			Belt - Fan & Alt.; W/150A. Alt. ....	4273188M1	▲K080685HD
Belt - Alt. ....	72161396	②7330	<b>RT145</b>		
<b>DT160</b>			<b>Cummins 6-Cyl. 5.9 L Diesel</b>		
<b>Cummins 6-Cyl. 8.3 L Diesel</b>			2004-2002		
2004-2002			Belt - Alt. ....	3288999	▲K080630HD
Belt - Alt. ....	3915768	▲K080733HD	Tensioner Assy. - Alt. ....	3937553	38504
Tensioner Assy. - Alt. ....	3937553	38504	<b>ST34A</b>		
<b>DT180A; DT200A</b>			<b>Iseki 3-Cyl. 91 Diesel</b>		
<b>AGCO 6-Cyl. 7.4 L Diesel</b>			2009		
2009-2008			Belt - Fan ....	3607417M1	▲9385HD
Belt - Serpentine - A.C. ....	4281345M1	▲K080433HD	<b>ST47A</b>		
Belt - Serpentine - Fan & Alt. ....	4284981M1	▲K080718HD	<b>Iseki 4-Cyl. 134 Diesel</b>		
<b>GT45A; GT55A</b>			2009		
<b>AGCO 3-Cyl. 183 Diesel</b>			Belt - Fan ....	6243082M1	▲9412HD
2008-2005			<b>ST52A</b>		
Belt - A.C.; W/31 1/8" Belt O.C. ....	72290486	7305	<b>Iseki 4-Cyl. 180 Diesel</b>		
Belt - A.C.; W/54 1/4" Belt O.C. ....	72278018	②▲9540HD	2009		
Belt - Alt. & W.P. ....	72272272	7485	Belt - Fan ....	6243082M1	▲9412HD
<b>GT65A; GT75A</b>			<b>ST60A</b>		
<b>AGCO 4-Cyl. 244 Diesel</b>			<b>Iseki 4-Cyl. 180 Diesel</b>		
2008-2005			2009		
Belt - A.C.; W/31 1/8" Belt O.C. ....	72290486	7305	Belt - Fan ....	4264647M1	▲9435HD
Belt - A.C.; W/54 1/4" Belt O.C. ....	72278018	②▲9540HD	<b>ALLIS-CHALMERS</b>		
Belt - Alt. & W.P. ....	72272272	7485	<b>4W 220</b>		
<b>LT75; LT90</b>			<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
<b>Cummins 4-Cyl. 4.5 L Diesel</b>			1984-1981		
2005-2004			Belt - A.C. ....	273705	▲9505HD
Belt - Alt. ....	3966783	▲K080590HD	Belt - Fan & Alt. ....	273193	②TR22664
Tensioner Assy. - Alt. ....	3937553	38504	<b>4W 305</b>		
Tensioner Pulley - Alt. ....		36091	<b>Allis-Chalmers 6-Cyl. 731 Diesel</b>		
<b>RT95</b>			1985-1981		
<b>Cummins 6-Cyl. 5.9 L Diesel</b>			Belt - A.C. ....	226935	▲9476HD
2004			Belt - Alt. ....	259401	TR22517
Belt - Alt. ....	3288878	▲K080594HD	Belt - Fan ....	273419	②TR28628
Tensioner Assy. - Alt. ....	3937556	38513	Belt - W.P. ....	4396941	7475
Tensioner Pulley - Alt. ....		36091	Hose - Upper ....		●26531
<b>2003-2002</b>			Hose - Lower ....		●26532
Belt - Alt. ....	3288878	▲K080594HD			

②Two Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>160</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1974-1972		
Belt - Fan & Gen.; W/48 1/4" Belt O.C.		▲9480HD
Belt - Fan & Gen.; W/50 1/4" Belt O.C.	2074320	▲9500HD
Belt - P.S.	2073746	▲9290HD
<b>170</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1973-1967		
Belt - Fan & Alt.	227470	▲9480HD
Hose - Upper		24228
Hose - Lower		☞20993
		or ●25480
<b>West Allis 4-Cyl. 226</b>		
1973-1967		
Belt - Fan & Alt.	248316	▲9470HD
Hose - Upper; Early		●25477
Hose - Upper; Late		●25482
Hose - Lower		20065
		or ●25473
Hose - By Pass		24212
<b>175</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1980-1970		
Belt - Fan & Alt.	227470	▲9480HD
Hose - Upper		24228
Hose - Lower		☞20993
		or ●25480
<b>Perkins 4-Cyl. 248 Diesel</b>		
1980-1970		
Hose - Upper		24228
Hose - Lower		☞20993
		or ●25480
<b>West Allis 4-Cyl. 226</b>		
1976-1973		
Belt - Fan & Alt.	248316	▲9470HD
Hose - Upper; Early		●25477
Hose - Upper; Late		●25482
Hose - Lower		20065
		or ●25473
Hose - By Pass		24212
<b>185</b>		
<b>West Allis 6-Cyl. 301 Diesel</b>		
1981-1970		
Belt - Fan & Alt.	243021	▲9530HD
Hose - Upper		21256
		or ●26504
Hose - Lower		●26504
<b>200</b>		
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
1975-1972		
Belt - A.C.	256417	▲9720HD
Belt - Fan & Alt.; W/52 3/4" Belt O.C.		②▲9525HD
Belt - Fan & Alt.; W/53 1/4" Belt O.C.	256655	②▲9530HD
Hose - Upper		☞21944
		or ●26505
<b>440</b>		
<b>Cummins 555C Diesel</b>		
1976-1972		
Belt - A.C.; W/40 3/4" Belt O.C.		▲9405HD
Belt - A.C.; W/41 1/4" Belt O.C.		▲9412HD
Belt - Alt.	178398	②7340
Belt - Fan & W.P.	204481	③▲9625HD
Hose - Upper		24432

Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>650; 652; 653; 655</b>		
<b>Allis-Chalmers 2000 Diesel</b>		
1975-1970		
Belt - Alt.	245120	▲9670HD
Belt - W.P.	237048	▲9455HD
Hose - Upper		☞20520
<b>5015</b>		
<b>Toyosha 3-Cyl. 61 Diesel</b>		
1985-1981		
Belt - Fan & Alt.	2100737	7380
Hose - Upper		20782
<b>5020</b>		
<b>Toyosha 2-Cyl. 77 Diesel</b>		
1985-1977		
Belt - Fan & Alt.	2097654	▲9400HD
Hose - Upper - Eng. To Pipe		20065
		or ●25472
Hose - Lower - Eng. To Pipe		●25252
<b>5030</b>		
<b>Toyosha 2-Cyl. 90 Diesel</b>		
1985-1978		
Belt - Fan & Alt.	2097654	▲9400HD
Hose - Upper		●25473
Hose - Lower		●25252
<b>5040</b>		
<b>Uzina 3-Cyl. 143 Diesel</b>		
1980-1976		
Belt - Fan & Alt.	2091561	7450
<b>5045</b>		
<b>Fiat 3-Cyl. 159 Diesel</b>		
1983-1981		
Belt - Fan & Alt.; Ser. No. 700,000 & After ...	2091561	7450
Hose - Upper		☞21794
		or ●25477
Hose - Lower - Eng. To Pipe		24224
Hose - Lower - Pipe To Rad.		24224
<b>5050</b>		
<b>Fiat 3-Cyl. 168 Diesel</b>		
1983-1977		
Belt - Fan & Alt.; Ser. No. 700,000 & After ...	2091561	7450
Belt - Fan & Alt.; Ser. No. 700,000 & Before	2091544	7445
Hose - Lower - Eng. To Pipe		24224
Hose - Lower - Pipe To Rad.		24224
<b>6040</b>		
<b>Perkins 3-Cyl. 152 Diesel</b>		
1974		
Belt - Fan, Alt. & W.P.	229211	▲9463HD
Hose - Upper		☞21174
		or ●25473
Hose - Lower		☞20808
Hose - By Pass		☞20573
<b>Perkins 3-Cyl. 153 Diesel</b>		
1975		
Belt - Fan, Alt. & W.P.	229211	▲9463HD
Hose - Upper		☞21174
		or ●25473
Hose - Lower		☞20808
Hose - By Pass		☞20573
<b>6060</b>		
<b>Allis-Chalmers 4-Cyl. 200 Diesel</b>		
1984-1980		
Belt - A.C.; Ser. No. 3770 & After	562203	▲9440HD
Belt - A.C.; Ser. No. 4373 & Before	272411	▲9447HD
Belt - Fan & Alt.	263408	▲9540HD

②Two Required ③Three Required ☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>6060 – Continued</b>		
Allis-Chalmers 4-Cyl. 200 Diesel – Continued		
1984-1980 – Continued		
Hose - Upper .....		≠21379 or ●26524
<b>6070</b>		
Allis-Chalmers 4-Cyl. 200 Diesel		
1985-1984		
Belt - A.C. ....	562203	▲9440HD
Belt - Fan & Alt. ....	263408	▲9540HD
<b>6080</b>		
Allis-Chalmers 4-Cyl. 200 Diesel		
1985-1980		
Belt - A.C.; Ser. No. 3769 & Before .....	272411	▲9447HD
Belt - A.C.; Ser. No. 4374 & After .....	562203	▲9440HD
Belt - Fan & Alt. ....	263408	▲9540HD
<b>6140</b>		
Toyosha 3-Cyl. 142 Diesel		
1985-1982		
Belt - Fan & Alt. ....		▲9440HD
Hose - Upper .....		≠21794 or ●25474
<b>7000</b>		
Allis-Chalmers 6-Cyl. 301 Diesel		
1979-1975		
Belt - A.C.; Ser. No. 8000 & Before .....	260149	9765
Belt - A.C.; Ser. No. 8001 & After .....	268485	▲9530HD
Belt - Fan & Alt. ....	260328	②▲9550HD
Hose - Upper .....		20401 or ●26525
Hose - By Pass .....		≠21942
<b>7010</b>		
Allis-Chalmers 6-Cyl. 301 Diesel		
1981-1979		
Belt - A.C. ....	260149	9765
Belt - Fan & Alt. ....		②▲9570HD
Hose - Upper .....		≠20401 or ●26524
Hose - Lower .....		●26531
<b>7020</b>		
Allis-Chalmers 6-Cyl. 301 Diesel		
1981-1977		
Belt - A.C. ....	260149	9765
Belt - Fan & Alt. ....		②▲9570HD
<b>7030</b>		
Allis-Chalmers 6-Cyl. 426 Diesel		
1974-1973		
Belt - A.C. ....	268485	▲9530HD
Belt - Fan & Alt. ....	267631	②TR20619
Hose - Upper .....		≠20731 or ●26523
Hose - Lower .....		24236
Hose - By Pass .....		≠20573
<b>7040</b>		
Allis-Chalmers 6-Cyl. 426 Diesel		
1977-1974		
Belt - A.C. ....	268485	▲9530HD
Belt - Fan & Alt. ....	267631	②TR20619
Hose - Upper .....		≠20731 or ●26523
Hose - Lower .....		24236
Hose - By Pass .....		≠20573

Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>7045</b>		
Allis-Chalmers 6-Cyl. 426 Diesel		
1981-1977		
Belt - A.C. ....	268485	▲9530HD
Belt - Fan & Alt. ....	267631	②TR20619
Hose - Upper .....		≠20731 or ●26523
Hose - Lower .....		24236
Hose - By Pass .....		≠20573
<b>7050</b>		
Allis-Chalmers 6-Cyl. 426 Diesel		
1974-1973		
Belt - A.C. ....	268485	▲9530HD
Belt - Fan & Alt. ....	267631	②TR20619
Hose - Upper .....		≠20731 or ●26523
Hose - Lower .....		24236
Hose - By Pass .....		≠20573
<b>7060</b>		
Allis-Chalmers 6-Cyl. 426 Diesel		
1981-1974		
Belt - A.C. ....	268485	▲9530HD
Belt - Fan & Alt. ....	267631	②TR20619
Hose - Upper .....		≠20731 or ●26523
Hose - Lower .....		24236
Hose - By Pass .....		≠20573
<b>7080</b>		
Allis-Chalmers 6-Cyl. 426 Diesel		
1981-1974		
Belt - A.C.; Ser. No. 3828 & Before .....	268485	▲9530HD
Belt - A.C.; Ser. No. 3829 & After .....	261802	▲9545HD
Belt - Fan & Alt. ....	269183	②TR22607
Hose - Upper .....		●26523
Hose - Lower .....		≠20756
Hose - By Pass .....		≠20065
<b>7580</b>		
Allis-Chalmers 6-Cyl. 426 Diesel		
1981-1976		
Belt - A.C.; Ser. No. 2611 & Before .....	268485	▲9530HD
Belt - A.C.; Ser. No. 2612 & After .....	261802	▲9545HD
Belt - Fan & Alt. ....	269183	②TR22607
Hose - Upper .....		≠21133
<b>8010</b>		
Allis-Chalmers 6-Cyl. 301 Diesel		
1985-1981		
Belt - A.C. ....	260149	9765
Belt - Fan & Alt. ....	254350	②▲9560HD
Hose - Upper .....		●26528
Hose - By Pass .....		≠20661 or ●25251
<b>8030</b>		
Allis-Chalmers 6-Cyl. 426 Diesel		
1985-1981		
Belt - A.C.; Ser. No. 1906 & Before .....	268485	▲9530HD
Belt - A.C.; Ser. No. 1907 & After .....	273705	▲9505HD
Belt - Fan & Alt. ....	273193	②TR22664
Hose - Upper .....		●26527
Hose - Lower .....		24440
Hose - By Pass .....		≠20065
<b>8050</b>		
Allis-Chalmers 6-Cyl. 426 Diesel		
1985-1981		
Belt - A.C.; Ser. No. 1836 & Before .....	268485	▲9530HD
Belt - A.C.; Ser. No. 1837 & After .....	273705	▲9505HD
Belt - Fan & Alt. ....	273193	②TR22664

②Two Required ≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>8070</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
1985-1981		
Belt - A.C.; Ser. No. 1350 & Before .....	268485	▲9530HD
Belt - A.C.; Ser. No. 1351 & After .....	273705	▲9505HD
Belt - Fan & Alt. ....	273193	②TR22664
Hose - Upper .....		③<21115
		or ●26527
<b>8550</b>		
<b>Allis-Chalmers 6-Cyl. 731 Diesel</b>		
1981-1977		
Belt - A.C.; Ser. No. 1635 & Before .....	259363	▲9451HD
Belt - A.C.; Ser. No. 1636 & After .....	256935	▲9480HD
Belt - Alt. ....	259401	TR22517
Belt - Fan .....	259566	②TR28616
Belt - W.P. ....	4395701	7465
Hose - Upper .....		●26531
Hose - Lower .....		●26532
Hose - By Pass .....		20351
<b>A</b>		
<b>Allis-Chalmers 4-Cyl. 461</b>		
1942-1936		
Belt - Fan .....	112019	TR26341
Belt - Fan & Gen. ....	AT210	TR28400
<b>Allis-Chalmers 4-Cyl. 510 Distillate</b>		
1942-1936		
Belt - Fan .....	112019	TR26341
Belt - Fan & Gen. ....	AT210	TR28400
<b>B</b>		
<b>Allis-Chalmers 4-Cyl. 116</b>		
1957-1937		
Belt - Fan .....	207003	TR22322
Belt - Fan & Gen.; W/34 1/8" Belt O.C. ....	215885	TR22336
Belt - Fan & Gen.; W/36 7/8" Belt O.C. ....	209656	TR22363
Hose - Upper .....		24220
Hose - Lower .....		24220
<b>Allis-Chalmers 4-Cyl. 125</b>		
1957-1937		
Belt - Fan .....	207003	TR22322
Belt - Fan & Gen.; W/34 1/8" Belt O.C. ....	215885	TR22336
Belt - Fan & Gen.; W/36 7/8" Belt O.C. ....	209656	TR22363
Hose - Upper .....		24220
Hose - Lower .....		24220
<b>Waukesha 4-Cyl. 113</b>		
1957-1937		
Belt - Fan .....	207003	TR22322
Belt - Fan & Gen.; W/34 1/8" Belt O.C. ....	215885	TR22336
Belt - Fan & Gen.; W/36 7/8" Belt O.C. ....	209656	TR22363
Hose - Upper .....		24220
Hose - Lower .....		24220
<b>C</b>		
<b>Allis-Chalmers 4-Cyl. 125</b>		
1950-1940		
Belt - Fan .....	207003	TR22322
Belt - Fan & Gen.; W/34 1/8" Belt O.C. ....	215885	TR22336
Belt - Fan & Gen.; W/36 7/8" Belt O.C. ....	209656	TR22363
Hose - Upper .....		24220
Hose - Lower .....		24220
<b>Allis-Chalmers 4-Cyl. 125 Distillate</b>		
1950-1940		
Belt - Fan .....	207003	TR22322
Belt - Fan & Gen.; W/34 1/8" Belt O.C. ....	215885	TR22336
Belt - Fan & Gen.; W/36 7/8" Belt O.C. ....	209656	TR22363
Hose - Upper .....		24220
Hose - Lower .....		24220

Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>CA</b>		
<b>Allis-Chalmers 4-Cyl. 125</b>		
1958-1950		
Belt - Fan & Gen. ....	209656	TR22363
Hose - Upper .....		24220
Hose - Lower .....		②24220
<b>D10</b>		
<b>Allis-Chalmers 4-Cyl. 138</b>		
1967-1959		
Belt - Fan & Gen.; Ser. No. D10-3501 & Before .....	209656	TR22363
Belt - Fan & Gen.; Ser. No. D10-3502 & After .....	233432	7380
Hose - Upper .....		③<20563
Hose - Lower .....		②24220
Hose - By Pass .....		28441
<b>Allis-Chalmers 4-Cyl. 149</b>		
1967-1959		
Belt - Fan & Gen.; Ser. No. D10-3501 & Before .....	209656	TR22363
Belt - Fan & Gen.; Ser. No. D10-3502 & After .....	233432	7380
Hose - Upper .....		③<20563
Hose - Lower .....		②24220
Hose - By Pass .....		28441
<b>D12</b>		
<b>Allis-Chalmers 4-Cyl. 138</b>		
1969-1959		
Belt - Fan & Gen.; Ser. No. D12-3001 & Before .....	209656	TR22363
Belt - Fan & Gen.; Ser. No. D12-3002 & After .....	233432	7380
Hose - Upper .....		③<20563
Hose - Lower .....		②24220
Hose - By Pass .....		28441
<b>Allis-Chalmers 4-Cyl. 149</b>		
1963-1959		
Belt - Fan & Gen.; Ser. No. D12-3001 & Before .....	209656	TR22363
Belt - Fan & Gen.; Ser. No. D12-3002 & After .....	233432	7380
Hose - Upper .....		③<20563
Hose - Lower .....		②24220
Hose - By Pass .....		28441
<b>D14</b>		
<b>Power-Crater 4-Cyl. 149</b>		
1960-1957		
Belt - Fan & Gen.; W/Electric Start .....	209656	TR22363
Belt - Fan & Gen.; W/O Electric Start .....	207003	TR22322
Hose - Upper .....		③<21942
		or ●25249
Hose - Lower .....		②24220
Hose - By Pass .....		28441
<b>Power-Crater 4-Cyl. 149 LPG</b>		
1960-1957		
Belt - Fan & Gen.; W/Electric Start .....	209656	TR22363
Belt - Fan & Gen.; W/O Electric Start .....	207003	TR22322
Hose - Upper .....		③<21942
		or ●25249
Hose - Lower .....		②24220
Hose - By Pass .....		28441
<b>D15</b>		
<b>Allis-Chalmers 4-Cyl. 175 Diesel</b>		
1962-1960		
Belt - Fan & Gen. ....	233489	②▲9420HD
Hose - Upper .....		24224
Hose - Lower .....		③<20267

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>D15 - Continued</b>		
<b>Power-Crater 4-Cyl. 149</b>		
1962-1960		
Belt - Fan & Gen. ....	233432	7380
Hose - Upper .....		≠20661
		or ●25251
<b>Power-Crater 4-Cyl. 149 LPG</b>		
1962-1960		
Belt - Fan & Gen. ....	233432	7380
<b>D15 Series II</b>		
<b>Allis-Chalmers 4-Cyl. 149</b>		
1967-1963		
Belt - Fan & Gen. ....	233432	7380
Hose - Upper .....		≠20661
		or ●25251
<b>Allis-Chalmers 4-Cyl. 175 Diesel</b>		
1967-1963		
Belt - Fan & Gen. ....	233489	②▲9420HD
Hose - Upper .....		24224
Hose - Lower .....		≠20267
<b>Power-Crater 4-Cyl. 160</b>		
1967-1963		
Hose - Upper .....		≠20661
		or ●25251
Hose - Lower .....		●25252
Hose - By Pass .....		28441
<b>D17</b>		
<b>Allis-Chalmers 4-Cyl. 226</b>		
1962-1957		
Belt - Fan & Gen. ....	229211	▲9463HD
Belt - P.S.; Ser. No. 42001 & After .....	237386	▲9425HD
Hose - Upper .....		≠20088
		or ●25474
Hose - Lower .....		≠21794
		or ●25476
Hose - By Pass .....		28442
<b>Allis-Chalmers 6-Cyl. 262 Diesel</b>		
1962-1957		
Belt - Fan & Gen.; Ser. No. 119938 & Before .....	229559	②▲9455HD
Belt - Fan & Gen.; Ser. No. 119939 & After ..	237048	▲9455HD
Belt - P.S. ....	235394	▲9375HD
Hose - Upper; Ser. No. 38964 & Before .....		②24228
Hose - Upper; Ser. No. 38965 & After .....		●26502
Hose - Lower; Ser. No. 38964 & Before .....		24224
Hose - Lower; Ser. No. 38965 & After .....		≠20559
		or ●25528
Hose - By Pass .....		24216
<b>D17 Series II</b>		
<b>Allis-Chalmers 4-Cyl. 226</b>		
1964-1962		
Belt - Fan & Gen. ....	229211	▲9463HD
Belt - P.S.; Ser. No. 42001 & After .....	237386	▲9425HD
Hose - Upper .....		≠20088
		or ●25474
Hose - Lower .....		≠21794
		or ●25476
Hose - By Pass .....		28442
<b>Allis-Chalmers 6-Cyl. 262 Diesel</b>		
1964-1962		
Belt - Fan & Gen.; Ser. No. 119938 & Before .....	229559	②▲9455HD
Belt - Fan & Gen.; Ser. No. 119939 & After ..	237048	▲9455HD
Belt - P.S. ....	235394	▲9375HD
Hose - Upper; Ser. No. 38964 & Before .....		②24228
Hose - Upper; Ser. No. 38965 & After .....		●26502
Hose - Lower; Ser. No. 38964 & Before .....		24224
Hose - Lower; Ser. No. 38965 & After .....		≠20559
		or ●25528

Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>D17 Series II - Continued</b>		
<b>Allis-Chalmers 6-Cyl. 262 Diesel - Continued</b>		
1964-1962 - Continued		
Hose - By Pass .....		24216
<b>D17 Series IV</b>		
<b>Allis-Chalmers 4-Cyl. 226</b>		
1967-1964		
Belt - Fan & Gen. ....	229211	▲9463HD
Belt - P.S.; Ser. No. 42001 & After .....	237386	▲9425HD
Hose - Upper .....		≠20088
		or ●25474
Hose - Lower .....		≠21794
		or ●25476
Hose - By Pass .....		28442
<b>Allis-Chalmers 6-Cyl. 262 Diesel</b>		
1967-1964		
Belt - Fan & Gen.; Ser. No. 119938 & Before .....	229559	②▲9455HD
Belt - Fan & Gen.; Ser. No. 119939 & After ..	237048	▲9455HD
Belt - P.S. ....	235394	▲9375HD
Hose - Upper .....		●26502
Hose - Lower .....		≠20559
		or ●25528
<b>D19</b>		
<b>Allis-Chalmers 6-Cyl. 262</b>		
1964-1961		
Belt - Fan & Gen.; W/46 1/4" Belt O.C. ....	235353	▲9463HD
Belt - Fan & Gen.; W/48 1/4" Belt O.C. ....	227470	▲9480HD
Belt - P.S. ....	235394	▲9375HD
Hose - Upper .....		●26502
Hose - Lower .....		≠20559
		or ●25528
<b>Allis-Chalmers 6-Cyl. 262 Diesel</b>		
1964-1961		
Belt - Fan & Gen.; W/46 1/4" Belt O.C. ....	235353	▲9463HD
Belt - Fan & Gen.; W/48 1/4" Belt O.C. ....	227470	▲9480HD
Belt - P.S. ....	235394	▲9375HD
Hose - Upper .....		●26502
Hose - Lower .....		●26502
<b>D21</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
1965-1963		
Belt - Fan & Alt.; Ser. No. 4445 & Before .....	240595	②▲9580HD
Belt - Fan & Alt.; Ser. No. 4446 & After .....	254350	▲9560HD
Hose - Upper .....		●26511
Hose - Lower .....		●26508
Hose - By Pass .....		●25257
<b>D21 Series II</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
1969-1965		
Belt - Fan & Alt.; Ser. No. 4445 & Before .....	240595	②▲9580HD
Belt - Fan & Alt.; Ser. No. 4446 & After .....	254350	▲9560HD
Hose - Upper .....		●26511
Hose - Lower .....		●26508
Hose - By Pass .....		●25257
<b>G</b>		
<b>Continental 4-Cyl. 62</b>		
1955-1948		
Belt - Fan & Gen. ....	800116	TR22416
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>H3</b>		
<b>Allis-Chalmers 4-Cyl. 149</b>		
1968-1963		
Belt - Fan & Gen. ....	233432	7380
Hose - Upper .....		≠20661

②Two Required ≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>H4</b>		
<b>Allis-Chalmers 4-Cyl. 200</b>		
1969-1965		
Belt - Fan & Alt.; W/45 3/4" Belt O.C. ....	237048	▲9455HD
Belt - Fan & Alt.; W/67 1/4" Belt O.C. ....	245120	▲9670HD
<b>HD3</b>		
<b>Allis-Chalmers 4-Cyl. 149</b>		
1968-1960		
Belt - Fan & Gen. ....	233432	7380
<b>Allis-Chalmers 4-Cyl. 175 Diesel</b>		
1968-1960		
Belt - Fan & Gen. ....	233490	②▲9420HD
Hose - Upper .....		②24224
Hose - Lower .....		②24224
<b>HD4</b>		
<b>Allis-Chalmers 4-Cyl. 200</b>		
1969-1965		
Belt - Fan & Alt.; W/45 3/4" Belt O.C. ....	237048	▲9455HD
Belt - Fan & Alt.; W/67 1/4" Belt O.C. ....	245120	▲9670HD
<b>HD5; HD5A; HD5B</b>		
<b>GM 2-Cyl. 142 Diesel</b>		
1955-1946		
Belt - Fan & Gen. ....	033138	②TR22625
Hose - Upper .....		24224
Hose - Lower .....		②24228
<b>HD6; HD6A; HD6B</b>		
<b>Allis-Chalmers 4-Cyl. 344 Diesel</b>		
1974-1955		
Belt - Fan; Ser. No. 13321 & Before .....	4348910	②TR28596
Belt - Fan; Ser. No. 13322 & After .....	4349777	②TR28483
Belt - Fan; Ser. No. 6-10368 & Before .....	4348910	②TR28596
Belt - Fan; Ser. No. 6-10369 & After .....	4349777	②TR28483
Belt - W.P. & Gen.; Ser. No. 13322 & After .	4349728	TR22514
Belt - W.P. & Gen.; Ser. No. 6-10368 & Before .....	4348851	TR28514
Belt - W.P. & Gen.; Ser. No. 6-10369 & After .....	4349729	TR22485
Hose - Upper .....		23547
Hose - Lower .....		23550
Hose - By Pass .....		24230
<b>HD6E</b>		
<b>Allis-Chalmers 4-Cyl. 344 Diesel</b>		
1974-1961		
Belt - Fan; Ser. No. 13321 & Before .....	4348910	②TR28596
Belt - Fan; Ser. No. 13322 & After .....	4349777	②TR28483
Belt - Fan; Ser. No. 6-10368 & Before .....	4348910	②TR28596
Belt - Fan; Ser. No. 6-10369 & After .....	4349777	②TR28483
Belt - W.P. & Gen.; Ser. No. 13322 & After .	4349728	TR22514
Belt - W.P. & Gen.; Ser. No. 6-10368 & Before .....	4348851	TR28514
Belt - W.P. & Gen.; Ser. No. 6-10369 & After .....	4349729	TR22485
Hose - Upper .....		23547
Hose - Lower .....		23550
Hose - By Pass .....		24230
<b>HD6EP</b>		
<b>Allis-Chalmers 4-Cyl. 344 Diesel</b>		
1974-1961		
Belt - Fan .....	4337756	②TR28514
Belt - W.P. & Gen. ....	4337725	TR22525
Hose - Upper .....		23547
Hose - Lower .....		24940
<b>HD7; HD7W</b>		
<b>GM 3-Cyl. 213 Diesel</b>		
1950-1940		
Belt - Fan .....	602944	②TR22578
Belt - Gen. ....	040549	TR20451

Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>HD9</b>		
<b>GM 4-Cyl. 284 Diesel</b>		
1955-1950		
Belt - Fan .....	033138	②TR22625
Belt - Gen.; Ser. No. 3270 & Before .....	079582	TR22405
Belt - Gen.; Ser. No. 3271 & After .....	040549	TR20451
Hose - Upper .....		24232
Hose - Lower .....		24232
Hose - By Pass .....		24216
<b>HD10; HD10W</b>		
<b>GM 4-Cyl. 284 Diesel</b>		
1950-1940		
Belt - Fan .....	602944	②TR22578
Belt - Gen. ....	040549	TR20451
Hose - Upper .....		24232
Hose - Lower .....		24236
<b>HD11</b>		
<b>Allis-Chalmers 6-Cyl. 516 Diesel</b>		
1970-1955		
Belt - Fan; Ser. No. 11-4854 & Before .....	4335452	②TR28649
Belt - Fan; Ser. No. 11-4855 & After .....	4349778	②TR28522
Belt - Fan; Ser. No. 13322 & After .....	4337757	②TR28545
Belt - W.P. & Gen.; Ser. No. 11-4855 & After .....	4349728	TR22514
Belt - W.P. & Gen.; Ser. No. 13322 & After .	4338212	TR22534
Hose - Upper; Ser. No. 6426 & Before .....		24934
Hose - Upper; Ser. No. 6427 & After .....		23547
Hose - Lower .....		24240
<b>HD11B</b>		
<b>Allis-Chalmers 6-Cyl. 516 Diesel</b>		
1974-1971		
Belt - Fan; Ser. No. 11-4854 & Before .....	4335452	②TR28649
Belt - Fan; Ser. No. 11-4855 & After .....	4349778	②TR28522
Belt - Fan; Ser. No. 13322 & After .....	4337757	②TR28545
Belt - W.P. & Gen.; Ser. No. 11-4855 & After .....	4349728	TR22514
Belt - W.P. & Gen.; Ser. No. 13322 & After .	4338212	TR22534
Hose - Upper; Ser. No. 6426 & Before .....		24934
Hose - Upper; Ser. No. 6427 & After .....		23547
Hose - Lower .....		24240
<b>HD11E</b>		
<b>Allis-Chalmers 6-Cyl. 516 Diesel</b>		
1971-1963		
Belt - Fan; Ser. No. 11-4854 & Before .....	4335452	②TR28649
Belt - Fan; Ser. No. 11-4855 & After .....	4349778	②TR28522
Belt - Fan; Ser. No. 13322 & After .....	4337757	②TR28545
Belt - W.P. & Gen.; Ser. No. 11-4855 & After .....	4349728	TR22514
Belt - W.P. & Gen.; Ser. No. 13322 & After .	4338212	TR22534
Hose - Upper; Ser. No. 6426 & Before .....		24934
Hose - Upper; Ser. No. 6427 & After .....		23547
Hose - Lower .....		24240
<b>HD11EP</b>		
<b>Allis-Chalmers 6-Cyl. 516 Diesel</b>		
1971-1961		
Belt - Fan; Ser. No. 11-4854 & Before .....	4335452	②TR28649
Belt - Fan; Ser. No. 11-4855 & After .....	4349778	②TR28522
Belt - Fan; Ser. No. 13322 & After .....	4337757	②TR28545
Belt - W.P. & Gen.; Ser. No. 11-4855 & After .....	4349728	TR22514
Belt - W.P. & Gen.; Ser. No. 13322 & After .	4338212	TR22534
Hose - Upper; Ser. No. 6426 & Before .....		24934
Hose - Upper; Ser. No. 6427 & After .....		23547
Hose - Lower .....		24240
<b>HD11ES</b>		
<b>Allis-Chalmers 6-Cyl. 516 Diesel</b>		
1973-1967		
Belt - Fan; Ser. No. 11-4854 & Before .....	4335452	②TR28649
Belt - Fan; Ser. No. 11-4855 & After .....	4349778	②TR28522
Belt - Fan; Ser. No. 13322 & After .....	4337757	②TR28545

②Two Required ▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>HD11ES – Continued</b>		
<b>Allis-Chalmers 6-Cyl. 516 Diesel – Continued</b>		
<b>1973-1967 – Continued</b>		
Belt - W.P. & Gen.; Ser. No. 11-4855 & After	4349728	TR22514
Belt - W.P. & Gen.; Ser. No. 13322 & After	4338212	TR22534
Hose - Upper; Ser. No. 6426 & Before		24934
Hose - Upper; Ser. No. 6427 & After		23547
Hose - Lower		24240
<b>HD11F</b>		
<b>Allis-Chalmers 6-Cyl. 516 Diesel</b>		
<b>1973-1971</b>		
Belt - Fan; Ser. No. 11-4854 & Before	4335452	②TR28649
Belt - Fan; Ser. No. 11-4855 & After	4349778	②TR28522
Belt - Fan; Ser. No. 13322 & After	4337757	②TR28545
Belt - W.P. & Gen.; Ser. No. 11-4855 & After	4349728	TR22514
Belt - W.P. & Gen.; Ser. No. 13322 & After	4338212	TR22534
Hose - Upper; Ser. No. 6426 & Before		24934
Hose - Upper; Ser. No. 6427 & After		23547
Hose - Lower		24240
<b>HD11S</b>		
<b>Allis-Chalmers 6-Cyl. 516 Diesel</b>		
<b>1973-1967</b>		
Belt - Fan; Ser. No. 11-4854 & Before	4335452	②TR28649
Belt - Fan; Ser. No. 11-4855 & After	4349778	②TR28522
Belt - Fan; Ser. No. 13322 & After	4337757	②TR28545
Belt - W.P. & Gen.; Ser. No. 11-4855 & After	4349728	TR22514
Belt - W.P. & Gen.; Ser. No. 13322 & After	4338212	TR22534
Hose - Upper; Ser. No. 6426 & Before		24934
Hose - Upper; Ser. No. 6427 & After		23547
Hose - Lower		24240
<b>HD14</b>		
<b>GM 6-Cyl. 426 Diesel</b>		
<b>1947-1939</b>		
Belt - Fan	602944	②TR22578
Belt - Gen.	040549	TR20451
<b>HD14C</b>		
<b>GM 6-Cyl. 426 Diesel</b>		
<b>1947-1939</b>		
Belt - Gen.	602944	TR22578
<b>HD15; HD15AC</b>		
<b>GM 6-Cyl. 426 Diesel</b>		
<b>1955-1950</b>		
Belt - Fan; W/O Torque Converter	069704	②B81
Belt - Gen.; W/O Torque Converter	602944	TR22578
Belt - Gen.; W/Torque Converter	076750	TR22588
Hose - Upper		②24236
Hose - Lower		24236
<b>HD16; HD16A; HD16AC</b>		
<b>Allis-Chalmers 6-Cyl. 844 Diesel</b>		
<b>1970-1955</b>		
Belt - Fan & Gen.	086979	②CX81
Belt - W.P.	4386813	TR22495
Hose - Upper; Ser. No. 5901 & After		②24244
Hose - Lower; Ser. No. 5901 & After		②24240
Hose - By Pass		24226
<b>HD16B</b>		
<b>Allis-Chalmers 6-Cyl. 844 Diesel</b>		
<b>1973-1961</b>		
Belt - Fan & Gen.	086979	②CX81
Belt - W.P.	4386813	TR22495
Hose - Upper; Ser. No. 5901 & After		②24244
Hose - Lower; Ser. No. 5901 & After		②24240
Hose - By Pass		24226

Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>HD16D; HD16DC; HD16DP</b>		
<b>Allis-Chalmers 6-Cyl. 844 Diesel</b>		
<b>1970-1955</b>		
Belt - Fan & Gen.	086979	②CX81
Belt - W.P.	4386813	TR22495
Hose - Upper; Ser. No. 5901 & After		②24244
Hose - Lower; Ser. No. 5901 & After		②24240
Hose - By Pass		24226
<b>HD19</b>		
<b>GM 6-Cyl. 426 Diesel</b>		
<b>1950-1947</b>		
Belt - Fan; Ser. No. 1802 & After	067529	②CX81
Belt - Gen.	602944	TR22578
Hose - Upper; Ser. No. 1801 & Before		②24236
Hose - Upper; Ser. No. 1802 & After		24236
Hose - Lower		24236
<b>HD20</b>		
<b>GM 6-Cyl. 660 Diesel</b>		
<b>1954-1951</b>		
Belt - Fan & Gen.	067529	②CX81
Hose - Upper		24244
Hose - Lower; Std. Models		②24244
Hose - Lower; W/Torque Converter		24244
Hose - By Pass		24220
<b>HD21; HD21A; HD21AC</b>		
<b>Allis-Chalmers 6-Cyl. 844 Diesel</b>		
<b>1969-1954</b>		
Belt - Fan; Ser. No. 9001 & Before	067529	②CX81
Belt - Gen.	082879	♣9530HD
Belt - W.P.	4386813	TR22495
Hose - Upper		24244
Hose - Lower		②24240
<b>HD21B</b>		
<b>Allis-Chalmers 6-Cyl. 844 Diesel</b>		
<b>1975-1969</b>		
Hose - Upper		24244
Hose - Lower		②24240
<b>HD41</b>		
<b>Cummins VT121710 Diesel</b>		
<b>1974-1970</b>		
Belt - Alt.; W/36 3/8" Belt O.C.	663945	TR22358
Belt - Alt.; W/39 1/8" Belt O.C.		TR22386
Belt - Fan	673606	③CX81
Belt - W.P.	178665	②TR28390
Hose - Upper - Eng. To Pipe		②24448
Hose - Upper - Pipe To Rad.		②24448
Hose - Lower - Eng. To Pipe		②24456
Hose - Lower - Pipe To Rad.		②24456
<b>I-40</b>		
<b>Allis-Chalmers 4-Cyl. 149</b>		
<b>1966-1964</b>		
Belt - Fan & Gen.	233432	7380
Hose - Upper		♣20563
Hose - Lower		②24224
<b>I-60</b>		
<b>Allis-Chalmers 4-Cyl. 160</b>		
<b>1966-1965</b>		
Belt - Fan & Gen.	233432	7380
Hose - Upper		♣20661
		or ●25251
<b>Allis-Chalmers 4-Cyl. 175 Diesel</b>		
<b>1966-1965</b>		
Belt - Fan & Gen.	233489	②♣9420HD
Hose - Upper		24224
Hose - Lower; Molded Hose		♣20267
Hose - Lower; Strt. Hose		24224

②Two Required ③Three Required ♣Cut to Fit ●Flexible Coolant Hose ♠Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>I-400</b>		
<b>Allis-Chalmers 4-Cyl. 149</b>		
1968-1966		
Belt - Fan & Gen. ....	233432	7380
Hose - Upper .....		②20563
Hose - Lower .....		②24224
<b>I-600</b>		
<b>Allis-Chalmers 4-Cyl. 160</b>		
1968-1966		
Belt - Fan & Gen. ....	233432	7380
Hose - Upper .....		②20661
		or ●25251
<b>Allis-Chalmers 4-Cyl. 175 Diesel</b>		
1968-1966		
Belt - Fan & Gen. ....	233489	②▲9420HD
Hose - Upper .....		24224
Hose - Lower; Molded Hose .....		②20267
Hose - Lower; Strt. Hose .....		24224
<b>IB</b>		
<b>Allis-Chalmers 4-Cyl. 116</b>		
1958-1939		
Belt - Fan .....	207003	TR22322
Belt - Fan & Gen. ....	209656	TR22363
Hose - Upper .....		24220
Hose - Lower .....		②24220
<b>Allis-Chalmers 4-Cyl. 125</b>		
1958-1939		
Belt - Fan .....	207003	TR22322
Belt - Fan & Gen. ....	209656	TR22363
Hose - Upper .....		24220
Hose - Lower .....		②24220
<b>One-Eighty</b>		
<b>West Allis 6-Cyl. 265</b>		
1973-1967		
Belt - Fan & Alt. ....	243021	▲9530HD
Hose - Upper .....		21256
		or ●26504
Hose - Lower .....		●26504
<b>West Allis 6-Cyl. 301 Diesel</b>		
1973-1967		
Belt - Fan & Alt. ....	243021	▲9530HD
Hose - Upper .....		21256
		or ●26504
Hose - Lower .....		●26504
<b>One-Ninety</b>		
<b>Allis-Chalmers 6-Cyl. 265</b>		
1973-1964		
Belt - A.C. ....	246618	▲9360HD
Belt - Fan & Alt.; Ser. No. 2G05728 & Before .....	243021	▲9530HD
Belt - Fan & Alt.; Ser. No. 2G05729 & After .	252145	▲9525HD
Hose - Upper; Ser. No. 14450 & Before .....		●26503
Hose - Upper; Ser. No. 14451 & After .....		21256
		or ●26504
Hose - Lower; Ser. No. 14450 & Before .....		●26503
Hose - Lower; Ser. No. 14451 & After .....		●26504
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
1973-1964		
Belt - A.C. ....	246618	▲9360HD
Belt - Fan & Alt.; Ser. No. 2D25950 & Before .....	252145	▲9525HD
Belt - Fan & Alt.; Ser. No. 2D25951 & After .	255200	▲9510HD
Hose - Upper; Ser. No. 14450 & Before .....		●26503
Hose - Upper; Ser. No. 14451 & After .....		21256
		or ●26504
Hose - Lower; Ser. No. 14450 & Before .....		●26503
Hose - Lower; Ser. No. 14451 & After .....		●26504

Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>One-Ninety XT</b>		
<b>Allis-Chalmers 6-Cyl. 301</b>		
1972-1965		
Belt - A.C. ....	246618	▲9360HD
Belt - Fan & Alt. ....	252145	▲9525HD
Hose - Upper; Ser. No. 14450 & Before .....		●26503
Hose - Upper; Ser. No. 14451 & After .....		21256
		or ●26504
Hose - Lower; Ser. No. 14450 & Before .....		●26503
Hose - Lower; Ser. No. 14451 & After .....		●26504
<b>Allis-Chalmers 6-Cyl. 301 Diesel</b>		
1972-1965		
Belt - A.C. ....	246618	▲9360HD
Belt - Fan & Alt.; Ser. No. 2D25950 & Before .....	252145	▲9525HD
Belt - Fan & Alt.; Ser. No. 2D25951 & After .	255200	▲9510HD
Hose - Upper; Ser. No. 14450 & Before .....		●26503
Hose - Upper; Ser. No. 14451 & After .....		21256
		or ●26504
Hose - Lower; Ser. No. 14450 & Before .....		●26503
Hose - Lower; Ser. No. 14451 & After .....		●26504
<b>One-Seventy</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1973-1967		
Belt - Fan & Alt. ....	227470	▲9480HD
Hose - Upper .....		24228
Hose - Lower .....		②20993
		or ●25480
<b>West Allis 4-Cyl. 226</b>		
1973-1967		
Belt - Fan & Alt. ....	248316	▲9470HD
Hose - Upper; Early .....		●25477
Hose - Upper; Late .....		●25482
Hose - Lower .....		20065
		or ●25473
Hose - By Pass .....		24212
<b>One-Sixty</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1971-1969		
Belt - Fan & Gen.; W/48 1/4" Belt O.C. ....		▲9480HD
Belt - Fan & Gen.; W/50 1/4" Belt O.C. ....	2074320	▲9500HD
Belt - P.S. ....	2073746	▲9290HD
<b>Two-Ten</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
1973-1970		
Belt - A.C.; W/81 1/4" Belt O.C. ....		9810
Belt - Fan & Alt. ....	254351	②▲9560HD
Hose - Upper; Early .....		●26505
Hose - Upper; Late .....		●26511
Hose - Lower; Early .....		●26504
Hose - Lower; Late .....		●26508
Hose - By Pass .....		●25257
<b>Two-Twenty</b>		
<b>Allis-Chalmers 6-Cyl. 426 Diesel</b>		
1973-1969		
Belt - A.C.; W/81 1/4" Belt O.C. ....		9810
Belt - Fan & Alt. ....	254351	②▲9560HD
Hose - Upper; Early .....		●26505
Hose - Upper; Late .....		●26511
Hose - Lower; Early .....		●26504
Hose - Lower; Late .....		●26508
Hose - By Pass .....		●25257
<b>U</b>		
<b>Continental 4-Cyl. 284 Distillate</b>		
1952-1929		
Belt - Fan .....	U2754	TR28514
Belt - Gen.; W/2 1/2" Dia. Pulley .....	212336	2240
Belt - Gen.; W/3 5/8" Dia. Pulley .....		9260
Hose - Upper .....		24232

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>U - Continued</b>		
<b>Continental 4-Cyl. 284 Distillate - Continued</b>		
1952-1929 - Continued		
Hose - Lower .....		24232
<b>Unimog 4-Cyl. 301 Distillate</b>		
1952-1929		
Belt - Fan .....	U2754	TR28514
Belt - Gen.; W/2 1/2" Dia. Pulley .....	212336	2240
Belt - Gen.; W/3 5/8" Dia. Pulley .....		9260
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>UC</b>		
<b>Continental 4-Cyl. 284</b>		
1941-1930		
Belt - Fan .....	U2754	TR28514
Belt - Gen.; W/2 1/2" Dia. Pulley .....	212336	2240
Belt - Gen.; W/3 5/8" Dia. Pulley .....		9260
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>Unimog 4-Cyl. 301</b>		
1941-1930		
Belt - Fan .....	U2754	TR28514
Belt - Gen.; W/2 1/2" Dia. Pulley .....	212336	2240
Belt - Gen.; W/3 5/8" Dia. Pulley .....		9260
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>WC</b>		
<b>Allis-Chalmers 4-Cyl. 201</b>		
1948-1933		
Belt - Fan .....	203073	TR22416
Belt - Fan & Gen. ....	209824	TR22461
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>Allis-Chalmers 4-Cyl. 201 Distillate</b>		
1948-1933		
Belt - Fan .....	203073	TR22416
Belt - Fan & Gen. ....	209824	TR22461
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>WD</b>		
<b>Allis-Chalmers 4-Cyl. 201</b>		
1953-1948		
Belt - Fan .....	203073	TR22416
Belt - Fan & Gen. ....	209824	TR22461
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>Allis-Chalmers 4-Cyl. 201 Distillate</b>		
1953-1948		
Belt - Fan .....	203073	TR22416
Belt - Fan & Gen. ....	209824	TR22461
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>WD45</b>		
<b>Allis-Chalmers 4-Cyl. 226</b>		
1957-1953		
Belt - Fan & Gen. ....	209824	TR22461
Belt - P.S. ....	227398	▲9590HD
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>Allis-Chalmers 6-Cyl. 230 Diesel</b>		
1957-1953		
Belt - Fan & Gen., Ser. No. 77855 & Before .....	226935	▲9476HD
Belt - Fan & Gen., Ser. No. 77856 & After ...	227470	▲9480HD
Belt - P.S. ....	227398	▲9590HD
Hose - Upper .....		②24228
Hose - Lower .....		24224

Application	OEM No.	Our No.
<b>ALLIS-CHALMERS - Continued</b>		
<b>WF</b>		
<b>Allis-Chalmers 4-Cyl. 201</b>		
1951-1937		
Belt - Fan .....	203073	TR22416
Belt - Fan & Gen. ....	209824	TR22461
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>WK</b>		
<b>Allis-Chalmers 4-Cyl. 510</b>		
1939		
Belt - Fan .....	203073	TR22416
Belt - Fan & Gen. ....	209824	TR22461
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>ANTONIO CARRARO</b>		
<b>5500; 7500</b>		
<b>Carraro 49 H.P.</b>		
2001		
Belt - Fan & Alt. ....		7385
<b>Carraro 64 H.P.</b>		
2001		
Belt - Fan & Alt. ....		7385
<b>7700</b>		
<b>Carraro 4-Cyl. Diesel</b>		
2001		
Belt - Fan & Alt. ....		7380
<b>Carraro 49 H.P.</b>		
2001		
Belt - Fan & Alt. ....		7385
<b>Carraro 64 H.P.</b>		
2001		
Belt - Fan & Alt. ....		7385
<b>8008</b>		
<b>Carraro 4-Cyl. Diesel</b>		
2001		
Belt - Fan & Alt. ....		7380
<b>Bitrac HS</b>		
<b>Carraro 2-Cyl. Diesel</b>		
2001		
Belt - Fan & Alt. ....		7375
Hose - Upper - Eng. To Thermostat .....		②20065
Hose - Lower .....		●25252
<b>BELARUS</b>		
<b>250A</b>		
<b>Vladimir 2-Cyl. 127 Diesel</b>		
1987-1979		
Belt - Gen. & Blower .....		7520
<b>250AS</b>		
<b>Vladimir 2-Cyl. 127 Diesel</b>		
1996-1985		
Belt - Gen. & Blower .....		7500
<b>310</b>		
<b>Belarus 2-Cyl. 127 Diesel</b>		
1996-1989		
Belt - Gen. & Blower .....		7500
<b>400A; 400AN</b>		
<b>Belarus 4-Cyl. 253 Diesel</b>		
1997-1977		
Belt - Alt. & Blower .....	D37E1308021	②7512

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>BELARUS - Continued</b>		
<b>405A; 405AN</b>		
Belarus 4-Cyl. 253 Diesel		
1997-1994		
Belt - Fan .....	D37E1308021	②7512
<b>420</b>		
Belarus 4-Cyl. 253 Diesel		
1983		
Belt - Alt. & Blower .....	D37E1308021	②7512
1982-1978		
Belt - Alt. & Blower .....	D37E1308021	②7512
Belt - Fan .....	D37E1308021	②7512
<b>420A; 420AN</b>		
Belarus 4-Cyl. 253 Diesel		
1997-1976		
Belt - Alt. & Blower .....		②7525
Belt - Fan .....	D37E1308021	②7512
<b>425A; 425AN</b>		
Belarus 4-Cyl. 253 Diesel		
1997-1994		
Belt - Fan .....	D37E1308021	②7512
<b>500</b>		
Belarus 4-Cyl. 290 Diesel		
1992-1977		
Belt - Fan & Alt. ....		TR24489
Hose - Upper .....		③<20065
Hose - Lower .....		③<20945
Hose - By Pass .....		24212
<b>502</b>		
Belarus 4-Cyl. 290 Diesel		
1988		
Belt - Alt. ....		♣9520HD
<b>505</b>		
Belarus 4-Cyl. 290 Diesel		
1997-1982		
Belt - Alt. ....		♣9520HD
<b>510</b>		
Belarus 4-Cyl. 289 Diesel		
2000-1998		
Belt - Alt. ....		♣9520HD
<b>520</b>		
Belarus 4-Cyl. 290 Diesel		
1988		
Belt - Alt. ....		♣9520HD
Belt - Fan & Alt. ....		TR24489
Hose - Upper .....		③<20065
Hose - Lower .....		③<20945
Hose - By Pass .....		24212
1987-1985		
Belt - Fan & Alt. ....		TR24489
Hose - Upper .....		③<20065
Hose - Lower .....		③<20945
Hose - By Pass .....		24212
1984		
Belt - Alt. ....		♣9520HD
Belt - Fan & Alt. ....		TR24489
Hose - Upper .....		③<20065
Hose - Lower .....		③<20945
Hose - By Pass .....		24212
1983-1979		
Belt - Fan & Alt. ....		TR24489
Hose - Upper .....		③<20065
Hose - Lower .....		③<20945
Hose - By Pass .....		24212

Application	OEM No.	Our No.
<b>BELARUS - Continued</b>		
<b>525</b>		
Belarus 4-Cyl. 289 Diesel		
1997-1989		
Belt - Alt. ....		♣9520HD
<b>530</b>		
Belarus 4-Cyl. 289 Diesel		
1997-1994		
Belt - Alt. ....		♣9520HD
<b>532</b>		
Belarus 4-Cyl. 290 Diesel		
1997-1994		
Belt - Alt. ....		♣9520HD
<b>560; 562</b>		
Belarus 4-Cyl. 290 Diesel		
1991-1981		
Belt - Alt.; W/A.C. ....		9279
Belt - Fan & A.C. ....		TR22508
Belt - Fan & Alt. ....		TR24515
Hose - Upper .....		③<21794
		or ●25474
Hose - Lower .....		③<21145
Hose - By Pass .....		24216
<b>570; 572</b>		
Belarus 4-Cyl. 290 Diesel		
1997-1991		
Belt - Alt. ....		♣9520HD
<b>611</b>		
Belarus 4-Cyl. 302 Diesel		
1992-1980		
Belt - Fan & Alt. ....		TR24578
Hose - Upper .....		24228
Hose - Lower - Eng. To Pipe .....		24230
Hose - Lower - Pipe To Rad. ....		24224
<b>800</b>		
Belarus 4-Cyl. 290 Diesel		
1997-1977		
Belt - Alt.; W/A.C. ....		9270
Belt - Fan & A.C. ....		♣9510HD
Belt - Fan & Alt. ....		7516
Hose - Upper .....		③<21794
		or ●25474
Hose - Lower .....		③<21145
Hose - By Pass .....		24216
<b>802</b>		
Belarus 4-Cyl. 290 Diesel		
1996-1977		
Belt - Alt.; W/A.C. ....		9270
Belt - Fan & A.C. ....		♣9510HD
Belt - Fan & Alt. ....		7516
Hose - Upper .....		③<21794
		or ●25474
Hose - Lower .....		③<21145
Hose - By Pass .....		24216
<b>805</b>		
Belarus 4-Cyl. 290 Diesel		
1997-1989		
Belt - Alt. ....		♣9520HD

②Two Required ③Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>BELARUS - Continued</b>		
<b>820</b>		
Belarus 4-Cyl. 290 Diesel		
1997-1996		
Belt - Alt. ....	▲9520HD	
1995-1979		
Belt - Alt. ....	▲9520HD	
Hose - Upper .....	●25474	
<b>822</b>		
Belarus 4-Cyl. 290 Diesel		
1993-1981		
Belt - Alt.; W/A.C. ....	9270	
Belt - Fan & A.C. ....	▲9510HD	
Belt - Fan & Alt. ....	7516	
Hose - Upper .....	≡21794	
	or ●25474	
Hose - Lower .....	≡21145	
Hose - By Pass .....	24216	
<b>825</b>		
Belarus 4-Cyl. 290 Diesel		
1997-1989		
Belt - Alt. ....	▲9520HD	
<b>900</b>		
Belarus 4-Cyl. 290 Diesel		
1997-1991		
Belt - Alt. ....	▲9520HD	
<b>902</b>		
Belarus 4-Cyl. 290 Diesel		
1997-1986		
Belt - Alt. ....	▲9520HD	
<b>905</b>		
Belarus 4-Cyl. 290 Diesel		
1997-1991		
Belt - Alt. ....	▲9520HD	
<b>925</b>		
Belarus 4-Cyl. 290 Diesel		
1997-1991		
Belt - A.C., Alt. & Idler .....	9279	
Belt - Alt. ....	▲9520HD	
Belt - Fan & Alt. ....	▲9510HD	
Hose - Upper .....	20065	
	or ●25473	
<b>1500</b>		
Belarus V-6 558 Diesel		
1986-1978		
Belt - Fan .....	②TR24597	
Belt - Fan To Alt. ....	▲9463HD	
Hose - Upper - Eng. To Pipe .....	24224	
Hose - Upper - Pipe To Rad. ....	24224	
Hose - Lower - Eng. To Pipe .....	24238	
Hose - Lower - Pipe To Rad. ....	24238	
<b>1770</b>		
Belarus V-6 558 Diesel		
1995-1986		
Belt - Air Brake Compr. ....	TR24449	
Belt - Fan .....	②TR24597	
Belt - Fan To Alt. ....	▲9451HD	
Belt - Fan, Alt. & A.C. ....	22490	TR22485
Hose - Upper .....	24226	
Hose - Lower .....	24238	

Application	OEM No.	Our No.
<b>BELARUS - Continued</b>		
<b>5111</b>		
Belarus 4-Cyl. 289 Diesel		
2002		
Belt - Alt. ....	▲9520HD	
1999-1998		
Belt - Alt. ....	▲9520HD	
<b>5111M</b>		
Belarus 4-Cyl. 289 Diesel		
2000		
Belt - Alt. ....	▲9520HD	
<b>5145</b>		
Belarus 4-Cyl. 289 Diesel		
2002		
Belt - Alt. ....	▲9520HD	
1999-1998		
Belt - Alt. ....	▲9520HD	
<b>5145M</b>		
Belarus 4-Cyl. 289 Diesel		
2000		
Belt - Alt. ....	▲9520HD	
<b>6311</b>		
Belarus 4-Cyl. 289 Diesel		
1999-1998		
Belt - Alt. ....	▲9520HD	
<b>6311M</b>		
Belarus 4-Cyl. 289 Diesel		
2000		
Belt - Alt. ....	▲9520HD	
<b>6345</b>		
Belarus 4-Cyl. 289 Diesel		
2008-2005		
Belt - Alt. ....	▲9520HD	
Belarus 4-Cyl. 290 Diesel		
1999-1996		
Belt - Alt. ....	▲9520HD	
<b>6345M</b>		
Belarus 4-Cyl. 290 Diesel		
2000		
Belt - Alt. ....	▲9520HD	
<b>8011</b>		
Belarus 4-Cyl. 290 Diesel		
2002		
Belt - Alt. ....	▲9520HD	
2000		
Belt - Alt. ....	▲9520HD	
1998-1997		
Belt - Alt. ....	▲9520HD	
<b>8011L</b>		
Belarus 4-Cyl. 290 Diesel		
2000-1997		
Belt - Alt. ....	▲9520HD	

②Two Required ≡Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>BELARUS - Continued</b>		
<b>8311</b>		
Belarus 4-Cyl. 289 Diesel		
1998-1997		
Belt - Alt. ....		▲9520HD
<b>8311S</b>		
Belarus 4-Cyl. 289 Diesel		
2000		
Belt - Alt. ....		▲9520HD
<b>8345</b>		
Belarus 4-Cyl. 289 Diesel		
2008-2000		
Belt - Alt. ....		▲9520HD
Belarus 4-Cyl. 290 Diesel		
2000-1996		
Belt - Alt. ....		▲9520HD
<b>9011</b>		
Belarus 4-Cyl. 290 Diesel		
1997		
Belt - Alt. ....		▲9520HD
<b>9011L</b>		
Belarus 4-Cyl. 290 Diesel		
1998-1996		
Belt - Alt. ....		▲9520HD
<b>9021</b>		
Belarus 4-Cyl. 290 Diesel		
1998		
Belt - Alt. ....		▲9520HD
1995		
Belt - Alt. ....		▲9520HD
<b>9311</b>		
Belarus 4-Cyl. 290 Diesel		
1998-1996		
Belt - Alt. ....		▲9520HD
<b>9345</b>		
Belarus 4-Cyl. 289 Diesel		
2008-2005		
Belt - Alt. ....		▲9520HD
2000-1996		
Belt - Alt. ....		▲9520HD
<b>9345S</b>		
Belarus 4-Cyl. 289 Diesel		
2000		
Belt - Alt. ....		▲9520HD
<b>BF AVERY</b>		
<b>R</b>		
Hercules 4-Cyl. 165		
1951-1939		
Belt - Fan & W.P. ....	RE684	TR24476
Belt - Gen. ....	KE1112	▲9335HD
Hose - Upper ....		24224
Hose - Lower ....		24224
<b>V</b>		
Hercules 4-Cyl. 65		
1952-1946		
Belt - Fan & Gen. ....	VT407	TR26353

Application	OEM No.	Our No.
<b>BIG BUD</b>		
<b>450/50</b>		
Cummins 6-Cyl. 1150 Diesel		
1980-1979		
Belt - A.C. ....		▲9600HD
Belt - Alt. ....	206996	K050370
Hose - Lower - Eng. To Pipe ....		24456
<b>525/50</b>		
Cummins 6-Cyl. 1150 Diesel		
1982-1979		
Belt - A.C. ....		▲9600HD
Belt - Alt. ....	206996	K050370
Hose - Lower - Eng. To Pipe ....		24456
<b>CASE</b>		
<b>200 Series</b>		
Case 4-Cyl. 127		
1960-1958		
Belt - Fan & Gen. ....	VT4886	TR24449
Hose - Upper ....		24228
Hose - Lower ....		②24228
<b>300 Series</b>		
Case 4-Cyl. 148		
1959-1956		
Belt - Fan & Gen. ....	VT4886	TR24449
Belt - P.S. ....	G46083	7270
Hose - Upper ....		24228
Hose - Lower ....		②24228
Continental 4-Cyl. 157 Diesel		
1959-1956		
Belt - Fan & Gen. ....	G11233	▲9447HD
Belt - P.S. ....	G46124	1230
Hose - Upper ....		24228
Hose - Lower ....		②24226
<b>310</b>		
Case 4-Cyl. 148		
1963-1957		
Belt - Fan & Gen.; Ser. No. 3008187 & Before ....	VT4886	TR24449
Belt - Fan & Gen.; Ser. No. 3008188 Thru 3012300 ....	G46222	TR24461
Belt - Fan & Gen.; Ser. No. 3012301 & After ....	G46238	▲9476HD
Belt - P.S. ....	G46083	7270
Hose - Upper ....		●26602
Hose - Lower ....		20357
		or ●26602
Case 4-Cyl. 188 Diesel		
1963-1958		
Belt - Fan & Gen.; Ser. No. 3008187 & Before ....	VT4886	TR24449
Belt - Fan & Gen.; Ser. No. 3008188 Thru 3012300 ....	G46222	TR24461
Belt - Fan & Gen.; Ser. No. 3012301 & After ....	G46238	▲9476HD
Belt - P.S. ....	G46083	7270
Hose - Upper ....		●26507
Hose - Lower ....		24228
<b>320</b>		
Continental 4-Cyl. 148		
1958-1957		
Belt - Fan & Gen. ....	VT4886	TR24449
Belt - Fan, Gen. & S.P. ....	G46083	7270
Hose - Upper ....		24228
Hose - Lower ....		②24228
<b>350</b>		
Case 4-Cyl. 188 Diesel		
1979-1970		
Belt - Fan & Alt. ....	G46238	▲9476HD

②Two Required   ➤Cut to Fit   ●Flexible Coolant Hose   ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>350 - Continued</b>		
<b>Case 4-Cyl. 188 Diesel - Continued</b>		
1979-1970 - Continued		
Hose - Upper .....		≈20206 or ●26507
Hose - Lower .....		②24228
<b>350 Utility</b>		
<b>Case 4-Cyl. 164</b>		
1958-1957		
Belt - Fan & Gen. ....	VT4886	TR24449
Belt - P.S. ....	G46083	7270
Hose - Upper .....		24228
Hose - Lower .....		②24228
<b>351</b>		
<b>Case 4-Cyl. 164</b>		
1958-1956		
Belt - Fan & Gen. ....	VT4886	TR24449
Belt - P.S. ....	G46083	7270
<b>380CK Industrial</b>		
<b>David Brown 3-Cyl. 164 Diesel</b>		
1980-1974		
Belt - Fan & P.S. ....		②7430
Belt - Fan To Alt. ....		7315
Hose - Upper - Pipe To Rad. ....		24226
<b>400 Series</b>		
<b>Case 4-Cyl. 148</b>		
1959-1958		
Belt - Fan & Gen. ....	011139AB	▲9490HD
Hose - Upper .....		24240
Hose - Lower .....		24228
<b>Case 4-Cyl. 251</b>		
1958-1955		
Belt - Fan & Gen. ....	011139AB	▲9490HD
Hose - Upper .....		24240
Hose - Lower .....		24228
<b>Case 4-Cyl. 251 Diesel</b>		
1958-1955		
Belt - Fan & Gen. ....	011139AB	▲9490HD
Hose - Upper .....		24240
Hose - Lower .....		24228
<b>Case 4-Cyl. 251 LPG</b>		
1958-1955		
Hose - Upper .....		24240
Hose - Lower .....		24228
<b>410B Industrial; 411B Industrial</b>		
<b>Case 4-Cyl. 148</b>		
1959-1958		
Belt - P.S. ....	G46083	7270
<b>420</b>		
<b>Case 4-Cyl. 148</b>		
1963-1959		
Belt - Fan & Gen. ....	G46222	TR24461
Hose - Upper .....		20357
		or ●26602
Hose - Lower .....		20357
		or ●26602
<b>420B Industrial</b>		
<b>Case 4-Cyl. 148</b>		
1960		
Belt - Fan & Gen. ....	G46222	TR24461
Hose - Upper .....		20357
		or ●26602
Hose - Lower .....		20357
		or ●26602

Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>420B Industrial - Continued</b>		
<b>Case 4-Cyl. 148 - Continued</b>		
1959-1955		
Belt - Fan & Gen. - Left Side .....	VT4886	TR24449
Belt - Fan & Gen. - Right Side .....	G46238	▲9476HD
Belt - Fan, Gen. & S.P. ....	G46083	7270
Hose - Upper .....		24228
Hose - Lower .....		②24228
<b>420C Industrial</b>		
<b>Case 4-Cyl. 148</b>		
1962-1960		
Belt - Fan & Gen. ....	G46238	▲9476HD
Hose - Upper .....		●26602
Hose - Lower .....		20357
		or ●26602
<b>Case 4-Cyl. 188 Diesel</b>		
1962-1960		
Belt - Fan & Gen. ....	G46238	▲9476HD
Hose - Upper .....		●26507
<b>430</b>		
<b>Case 4-Cyl. 148</b>		
1969-1960		
Belt - Fan & Gen. ....	G46238	▲9476HD
Hose - Upper .....		24228
Hose - Lower; Ser. No. 6169602 & Before .....		②24228
Hose - Lower; Ser. No. 6169603 & After .....		≈20957
		or ●26602
<b>Case 4-Cyl. 188 Diesel</b>		
1969-1960		
Belt - Fan & Gen. ....	G46238	▲9476HD
Hose - Upper .....		24232
Hose - Lower .....		24228
<b>441</b>		
<b>Case 4-Cyl. 148</b>		
1960		
Belt - Fan & Gen. ....	G46238	▲9476HD
Hose - Upper .....		24228
Hose - Lower; Ser. No. 6169602 & Before .....		②24228
Hose - Lower; Ser. No. 6169603 & After .....		≈20957
		or ●26602
<b>450</b>		
<b>Case 4-Cyl. 188 Diesel</b>		
1979-1965		
Belt - Fan & Gen. ....	G46238	▲9476HD
Hose - Upper .....		≈20611
		or ●26508
Hose - Lower .....		24228
		or ●26508
<b>450B</b>		
<b>Case 4-Cyl. 188</b>		
1984-1978		
Hose - Upper .....		≈20611
		or ●26508
Hose - Lower .....		≈20957
		or ●26603
<b>475</b>		
<b>Case 301BD Diesel</b>		
1986-1972		
Belt - Fan & Alt. ....	L49006	②▲9570HD
Hose - Upper .....		●26530
Hose - Lower .....		●26529
Hose - By Pass .....		24220
<b>480B Industrial</b>		
<b>Case 4-Cyl. 188 Diesel</b>		
1975-1966		
Belt - Fan & Alt. ....	A38824	▲9490HD

②Two Required ≈Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>484</b>		
<b>Case 3-Cyl. 179 Diesel</b>		
1984-1978		
Belt - Fan & Alt.; W/61" Belt O.C.	3129140R1	▲9610HD
Belt - Fan & Alt.; W/62" Belt O.C.	3113329R1	▲9620HD
<b>500</b>		
<b>Case 6-Cyl. 377 Diesel</b>		
1956-1953		
Belt - Fan & Gen.	09802AB	TR28492
Belt - P.S.	010288AB	7270
Hose - Upper		24224
Hose - Lower		24236
<b>500B</b>		
<b>Continental ED208 Diesel</b>		
1959-1958		
Belt - Fan & Gen.	VT4886	TR24449
Belt - P.S.	G46083	7270
<b>Continental F209</b>		
1959-1957		
Belt - Fan & Gen.	VT4886	TR24449
Belt - P.S.	G46083	7270
Hose - Upper		24228
Hose - Lower		②24228
<b>520</b>		
<b>Continental 4-Cyl. 157 Diesel</b>		
1963-1959		
Belt - Fan & Gen.	30353	TR24449
<b>Continental 4-Cyl. 162</b>		
1960-1959		
Belt - Fan & Gen.	11585	TR24465
Hose - Lower		②20230
		or ●25478
<b>530; 540</b>		
<b>Case 4-Cyl. 159</b>		
1969-1960		
Belt - Fan & Gen.	G46238	▲9476HD
Hose - Upper		24232
Hose - Lower; Ser. No. 6169603 & Before		24228
Hose - Lower; Ser. No. 6169604 & After		②20957
<b>Case 4-Cyl. 188 Diesel</b>		
1969-1960		
Belt - Fan & Gen.	G46238	▲9476HD
Hose - Upper		24232
Hose - Lower		24228
<b>550G</b>		
<b>Case 4-Cyl. 390 Diesel</b>		
2000-1997		
Belt - Fan & Alt.	J911563	▲K080605HD
<b>600</b>		
<b>Case 6-Cyl. 377 Diesel</b>		
1957		
Belt - Fan & Gen.	09802AB	TR28492
Belt - P.S.	010288AB	7270
Hose - Upper		24224
Hose - Lower		24236
<b>600 Crawler</b>		
<b>Continental ED208 Diesel</b>		
1962-1957		
Belt - Fan & Gen.; Ser. No. 7060734 & Before	10148	▲9430HD
Belt - Fan & Gen.; Ser. No. 7060735 & After	R12232	▲9440HD

Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>600 Crawler - Continued</b>		
<b>Continental F209</b>		
1962-1957		
Belt - Fan & Gen.; W/47" Belt O.C.	11585	TR24465
Belt - Fan & Gen.; W/48 3/4" Belt O.C.	31170	TR28483
Hose - Lower		②20230
		or ●25478
<b>600B</b>		
<b>Continental ED208 Diesel</b>		
1962-1957		
Belt - Fan & Gen.	VT4886	TR24449
Belt - P.S.	G46083	7270
<b>Continental F209</b>		
1962-1957		
Belt - Fan & Gen.	VT4886	TR24449
Belt - P.S.	G46083	7270
Hose - Upper		24228
Hose - Lower		②24228
<b>610 Crawler</b>		
<b>Continental ED208 Diesel</b>		
1962-1957		
Belt - Fan & Gen.; Ser. No. 7060734 & Before	10148	▲9430HD
Belt - Fan & Gen.; Ser. No. 7060735 & After	R12232	▲9440HD
<b>630</b>		
<b>Case 4-Cyl. 188</b>		
1963-1960		
Belt - Fan & Gen.	G46238	▲9476HD
Hose - Upper		24232
Hose - Lower; Ser. No. 6169603 & Before		24228
Hose - Lower; Ser. No. 6169604 & After		②20957
<b>Case 4-Cyl. 188 Diesel</b>		
1963-1960		
Belt - Fan & Gen.	G46238	▲9476HD
Hose - Upper		24232
Hose - Lower		24228
<b>640</b>		
<b>Case 4-Cyl. 188</b>		
1963-1960		
Belt - Fan & Gen.	G46238	▲9476HD
Hose - Upper		24232
Hose - Lower; Ser. No. 6169603 & Before		24228
Hose - Lower; Ser. No. 6169604 & After		②20957
<b>640C</b>		
<b>Case 4-Cyl. 188</b>		
1960		
Belt - Fan & Gen.	G46238	▲9476HD
Hose - Upper		24232
Hose - Lower; Ser. No. 6169603 & Before		24228
Hose - Lower; Ser. No. 6169604 & After		②20957
<b>650G</b>		
<b>Case 4-Cyl. 390 Diesel</b>		
2000-1995		
Belt - A.C.	S82985	②▲9365HD
Belt - Fan & Alt.	J911559	▲K080620HD
<b>700 Series</b>		
<b>Case 4-Cyl. 267 Diesel</b>		
1960-1958		
Belt - Fan & Gen.	A11444	▲9505HD
Belt - P.S.	A11441	7290
Hose - Upper		24240
Hose - Lower		●26508
Hose - By Pass		24224

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>730</b>		
<b>Case 4-Cyl. 251</b>		
1969-1960		
Belt - Fan & Gen. ....	A21457	②▲9505HD
Belt - P.S.; Ser. No. 8173400 & Before .....	A11441	7290
Belt - P.S.; Ser. No. 8173401 & After .....	A22765	7320
Hose - Upper .....		24240
Hose - Lower .....		●26509
<b>Case 4-Cyl. 267 Diesel</b>		
1969-1960		
Belt - Fan & Gen. ....	A21457	②▲9505HD
Belt - P.S.; Ser. No. 8173400 & Before .....	A11441	7290
Belt - P.S.; Ser. No. 8173401 & After .....	A22765	7320
Hose - Upper .....		24240
Hose - Lower .....		●26509
<b>741; 741C</b>		
<b>Case 4-Cyl. 251</b>		
1960		
Belt - Fan & Gen. ....	A21457	②▲9505HD
Belt - P.S.; Ser. No. 8173400 & Before .....	A11441	7290
Belt - P.S.; Ser. No. 8173401 & After .....	A22765	7320
Hose - Upper .....		24240
Hose - Lower .....		●26509
<b>750</b>		
<b>Case A267D Diesel</b>		
1967-1961		
Belt - Fan & Gen. ....	A19920	②TR22545
Hose - Lower .....		●26511
<b>770</b>		
<b>Case 4-Cyl. 251</b>		
1972-1969		
Belt - A.C. ....		▲9720HD
Belt - Fan & Alt. ....	A59762	TR22607
Hose - Upper .....		≠20760
Hose - Lower .....		●26530
Hose - By Pass .....		24220
<b>Case 4-Cyl. 267 Diesel</b>		
1972-1969		
Belt - A.C. ....		▲9720HD
Belt - Fan & Alt. ....	A59762	TR22607
Hose - Upper .....		24240
Hose - Lower .....		≠20731
		or ●26521
Hose - By Pass .....		24220
<b>780 Industrial</b>		
<b>Case A336BD Diesel</b>		
1981-1971		
Belt - Air Brake Compr. ....	L47236	7440
Belt - Fan & Alt. ....	L19082	▲9550HD
Hose - Upper .....		24240
Hose - Lower .....		●26531
Hose - By Pass .....		24220
<b>800</b>		
<b>Continental HD277 Diesel</b>		
1959-1957		
Belt - Fan & Gen. ....	R17746	TR24530
Hose - Upper; W/H.D. Rad. ....		≠20046
Hose - Upper; W/Std. Rad. ....		●26501
Hose - Upper; W/Tropical Rad. ....		●26502
Hose - Lower .....		②24224
<b>800 Series</b>		
<b>Case 4-Cyl. 267 Diesel</b>		
1959-1958		
Belt - Fan & Gen. ....	A11444	▲9505HD
Belt - P.S. ....	A11441	7290
Hose - Upper .....		24240
Hose - Lower .....		●26508

Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>800 Series - Continued</b>		
<b>Case 4-Cyl. 267 Diesel - Continued</b>		
1959-1958 - Continued		
Hose - By Pass .....		24224
<b>810</b>		
<b>Continental HD277 Diesel</b>		
1959-1957		
Belt - Fan & Gen. ....	R17746	TR24530
Hose - Upper; W/H.D. Rad. ....		≠20046
Hose - Upper; W/Std. Rad. ....		●26501
Hose - Upper; W/Tropical Rad. ....		●26502
Hose - Lower .....		②24224
<b>830</b>		
<b>Case 4-Cyl. 284</b>		
1969-1960		
Belt - Fan & Gen. ....	A21457	②▲9505HD
Belt - P.S.; Ser. No. 8173400 & Before .....	A11441	7290
Belt - P.S.; Ser. No. 8173401 & After .....	A22765	7320
Hose - Upper .....		24236
Hose - Lower .....		≠20611
		or ●26509
<b>Case 4-Cyl. 301 Diesel</b>		
1969-1960		
Belt - Fan & Gen. ....	A21457	②▲9505HD
Belt - P.S.; Ser. No. 8173400 & Before .....	A11441	7290
Belt - P.S.; Ser. No. 8173401 & After .....	A22765	7320
Hose - Upper .....		24236
Hose - Lower .....		≠20611
		or ●26509
<b>841; 841C; 841CK</b>		
<b>Case 4-Cyl. 284</b>		
1963-1960		
Belt - Fan & Gen. ....	A21457	②▲9505HD
Belt - P.S.; Ser. No. 8173400 & Before .....	A11441	7290
Belt - P.S.; Ser. No. 8173401 & After .....	A22765	7320
Hose - Upper .....		24240
Hose - Lower .....		●26509
<b>850</b>		
<b>Case A301BD Diesel</b>		
1981-1967		
Belt - Fan & Alt. ....	D43913	②TR22545
Hose - Upper .....		≠20760
Hose - Lower .....		●26511
Hose - By Pass .....		24220
<b>850B</b>		
<b>Case A336BD Diesel</b>		
1981-1977		
Hose - Lower - Eng. To Pipe .....		24444
<b>850G</b>		
<b>Case 6-Cyl. 590 Diesel</b>		
2000-1995		
Belt - A.C. ....	S82985	②▲9365HD
Belt - Fan & Alt. ....	J911559	▲K080620HD
<b>870</b>		
<b>Case 4-Cyl. 301</b>		
1974-1969		
Hose - Upper .....		≠20760
Hose - Lower .....		●26530
Hose - By Pass .....		24220
<b>Case 4-Cyl. 336 Diesel</b>		
1974-1969		
Belt - A.C. ....	A65717	▲9720HD
Belt - Fan & Alt. ....	A59762	TR22607
Hose - Upper .....		24240
Hose - Lower .....		≠21115
		or ●26530

②Two Required ≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>870 - Continued</b>		
<b>Case 4-Cyl. 336 Diesel - Continued</b>		
1974-1969 - Continued		
Hose - By Pass .....		24220
<b>900 Series</b>		
<b>Case 6-Cyl. 377 Diesel</b>		
1959-1957		
Belt - Fan & Gen. ....	011139AB	▲9490HD
Belt - P.S. ....	010288AB	7270
Hose - Upper .....		24240
Hose - Lower .....		24236
Hose - By Pass .....		24224
<b>Case 6-Cyl. 377 LPG</b>		
1959-1957		
Belt - Fan & Gen. ....	011139AB	▲9490HD
Belt - P.S. ....	010288AB	7270
Hose - Upper .....		24240
Hose - Lower .....		24236
Hose - By Pass .....		24224
<b>910</b>		
<b>Case 6-Cyl. 377 LPG</b>		
1959-1957		
Belt - Fan & Gen. ....	011139AB	▲9490HD
Belt - P.S. ....	010288AB	7270
Hose - Upper .....		24240
Hose - Lower .....		24236
Hose - By Pass .....		24224
<b>930</b>		
<b>Case 6-Cyl. 377</b>		
1969-1960		
Belt - Fan & Gen. ....	A21461	②▲9490HD
Belt - P.S. ....	A22766	7300
Hose - Upper .....		24240
Hose - Lower .....		●26521
<b>Case 6-Cyl. 377 LPG</b>		
1969-1960		
Belt - Fan & Gen. ....	A21461	②▲9490HD
Belt - P.S. ....	A22766	7300
Hose - Upper .....		24240
Hose - Lower .....		●26521
<b>Case 6-Cyl. 401 Diesel</b>		
1969-1960		
Belt - Fan & Gen. ....	A21461	②▲9490HD
Belt - P.S. ....	A22766	7300
Hose - Upper .....		24240
Hose - Lower .....		●26521
<b>940</b>		
<b>Case 6-Cyl. 377 LPG</b>		
1969-1960		
Belt - Fan & Gen. ....	A21461	②▲9490HD
Belt - P.S. ....	A22766	7300
<b>970</b>		
<b>Case 6-Cyl. 377</b>		
1978-1969		
Hose - Lower; Ser. No. 8675001 & Before .....		●26530
<b>Case 6-Cyl. 401 Diesel</b>		
1978-1969		
Belt - A.C.; Ser. No. 8693001 Thru 8705614 .....	A65717	▲9720HD
Belt - Fan & Alt. ....	A65143	TR22588
Hose - Upper; Ser. No. 8675002 & After .....		②<20970
		or ●26530
Hose - Lower; Ser. No. 8675001 & Before .....		●26530
Hose - By Pass .....		24220

Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>1000; 1010</b>		
<b>Continental JD382 Diesel</b>		
1965-1957		
Belt - Fan & Gen.; Ser. No. 7101202 & After .....	R17745	TR28596
Belt - Fan & Gen.; W/53 5/8" Belt O.C.; Ser. No. 7101201 & Before .....	R17746	TR24530
Belt - Fan & Gen.; W/58 3/4" Belt O.C.; Ser. No. 7101201 & Before .....	73430	TR28583
Hose - Upper .....		②<20046
		or ●26501
Hose - Lower; Ser. No. 7101201 & Before .....		②24224
Hose - Lower; Ser. No. 7101202 & After .....		●25478
<b>1030</b>		
<b>Case 6-Cyl. 451 Diesel</b>		
1969-1966		
Belt - Fan & Gen.; Ser. No. 8310335 & Before .....		②▲9530HD
Belt - Fan & Gen.; Ser. No. 8310336 & After .....	A57123	②TR22534
Belt - P.S.; Ser. No. 8310335 & After .....		TR22607
Belt - P.S.; Ser. No. 8310335 & Before .....	A34359	7550
Hose - Upper; W/60170, 60171 Rad. ....		②<20760
Hose - Upper; W/O 60170, 60171 Rad. ....		●26529
Hose - Lower .....		●26516
<b>1070</b>		
<b>Case 6-Cyl. 451 Diesel</b>		
1978-1969		
Belt - Fan & Alt.; W/59 1/8" Belt O.C. ....	A65143	TR22588
Belt - Fan & Alt.; W/73 1/4" Belt O.C. ....	A62962	▲9730HD
Hose - Upper .....		②<20970
		or ●26530
Hose - Lower .....		●26530
Hose - By Pass .....		24220
<b>1090</b>		
<b>Case 6-Cyl. 451 Diesel</b>		
1971-1970		
Belt - A.C.; Ser. No. 8693000 & Before .....	A65717	▲9720HD
Belt - Fan & Alt.; W/59 1/8" Belt O.C. ....	A65143	TR22588
Belt - Fan & Alt.; W/73 1/4" Belt O.C. ....	A62962	▲9730HD
<b>1150</b>		
<b>Case A401BD Diesel</b>		
1972-1965		
Belt - Fan & Gen. ....	D43913	②TR22545
Hose - Lower .....		●26511
<b>1150B</b>		
<b>Case 451BD Diesel</b>		
1978-1973		
Hose - Upper .....		●26530
Hose - Lower .....		●26532
Hose - By Pass .....		24220
<b>1150G</b>		
<b>Case 6T590 Diesel</b>		
2000-1997		
Belt - A.C. ....	S82985	②▲9365HD
Belt - Fan & Alt. ....	J911559	▲K080620HD
<b>1170</b>		
<b>Case 6-Cyl. 451 Diesel</b>		
1971-1970		
Belt - A.C. ....	A62962	▲9720HD
Belt - Fan & Alt. ....		TR22588
Hose - Upper .....		②<20970
		or ●26530
Hose - Lower .....		●26529
Hose - By Pass .....		24220

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>1175</b>		
<b>Case 6-Cyl. 451 Diesel</b>		
1978-1971		
Belt - Fan & Alt. ....	A65143	TR22588
Hose - Upper .....		②<20970
		or ●26530
Hose - Lower .....		●26529
Hose - By Pass .....		24220
<b>1190</b>		
<b>Case 3-Cyl. 164 Diesel</b>		
1983-1980		
Belt - Alt. ....		7320
Belt - Fan .....	K949311	7512
Belt - Fan & Hyd. Pump .....		②7425
Belt - W.P. & Alt. ....	K949311	7512
Hose - Upper .....		24224
<b>1194</b>		
<b>Case 3-Cyl. 164 Diesel</b>		
1985-1983		
Belt - Fan & P.S. ....		②7430
Belt - Fan To Alt. ....		7320
Hose - Upper .....		24224
<b>1200 Traction King</b>		
<b>Case 6-Cyl. 451 Diesel</b>		
1969-1964		
Belt - Fan & Gen. ....		②▲9530HD
Belt - V.P. ....	L10746	7440
Hose - Upper .....		24240
Hose - By Pass .....		24224
<b>1270</b>		
<b>Case 6-Cyl. 451 Diesel</b>		
1978-1971		
Belt - A.C. ....	A65716	▲9720HD
Belt - Fan & Alt. ....	A65143	TR22588
Hose - Lower .....		●26536
<b>1290</b>		
<b>Case 4-Cyl. 195 Diesel</b>		
1984-1980		
Belt - Fan & Alt. ....	K68073	7465
Hose - Upper .....		24224
<b>1294</b>		
<b>Case 4-Cyl. 219 Diesel</b>		
1985-1983		
Belt - Fan & Alt. ....		7470
Hose - Upper; Molded Hose .....		●25474
Hose - Upper; Strt. Hose .....		24224
<b>1370</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1978-1971		
Belt - A.C. ....	A65716	▲9720HD
Belt - Fan & Alt. ....	A65143	TR22588
Hose - Upper .....		②<20970
		or ●26530
<b>1390</b>		
<b>Case 4-Cyl. 219 Diesel</b>		
1983-1980		
Belt - Fan & Alt. ....	K68073	7465
Hose - Upper .....		24224
<b>1394</b>		
<b>Case 4-Cyl. 219 Diesel</b>		
1990-1983		
Belt - Fan & Alt. ....		7460
Hose - Upper; Molded Hose .....		●25474
Hose - Upper; Strt. Hose .....		24224

Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>1410</b>		
<b>David Brown 4-Cyl. 219 Diesel</b>		
1980-1976		
Belt - Fan & Alt. ....	K68073	7465
Hose - Upper .....		●25480
<b>1412</b>		
<b>David Brown 4-Cyl. 219 Diesel</b>		
1977-1975		
Belt - Fan & Alt. ....	K68073	7465
<b>1470 Traction King</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1972-1968		
Belt - A.C.; Early .....	T39995	②▲9400HD
Belt - A.C.; W/Idler .....	A65716	▲9730HD
Belt - Fan & Alt. ....	T38546	②TR22657
Hose - Upper .....		●26531
Hose - Lower .....		●26530
Hose - By Pass .....		24220
<b>1490</b>		
<b>Case 4-Cyl. 219 Diesel</b>		
1983-1980		
Belt - Fan & Alt. ....	K68073	7465
<b>1494</b>		
<b>Case 4-Cyl. 219 Diesel</b>		
1990-1983		
Belt - A.C. ....	K307429	▲9400HD
Belt - Fan & Alt.; W/A.C. ....	K308448	▲9490HD
Belt - Fan & Alt.; W/O A.C. ....	K68073	7465
<b>1570</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1978-1976		
Belt - A.C. ....	A65716	▲9720HD
Belt - Fan & Alt. ....	A65143	TR22588
Hose - Upper .....		●26530
Hose - By Pass .....		24220
<b>1594</b>		
<b>Case 6-Cyl. 329 Diesel</b>		
1990-1983		
Belt - A.C. ....		▲9520HD
Belt - Fan .....		7508
Belt - W.P. & Alt. ....		7500
Hose - Upper .....		●25484
<b>1690</b>		
<b>Case 6-Cyl. 329 Diesel</b>		
1984-1980		
Belt - A.C. ....	A162484	②▲9670HD
Belt - Fan .....	K949311	7512
Belt - W.P. & Alt. ....	K949311	7512
<b>2090</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1983-1978		
Belt - A.C. ....	A9628	▲9447HD
Belt - Fan & Alt. ....	A145325	②TR22607
Hose - Upper .....		②<21115
Hose - Lower .....		●26536
Hose - By Pass .....		24220
<b>2094</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1984-1983		
Belt - Fan & Alt.; W/A.C. ....	A145325	②TR22607
Belt - Fan & Alt.; W/O A.C. ....	A57130	TR22607
Belt - Fan To A.C. ....	A9628	▲9447HD
Hose - Upper .....		②<21115
Hose - Lower .....		●26536

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>2094 - Continued</b>		
<b>Case 6-Cyl. 504 Diesel - Continued</b>		
1984-1983 - Continued		
Hose - By Pass .....		24220
<b>2290</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1983-1978		
Belt - A.C. ....	A9628	▲9447HD
Belt - Fan & Alt. ....	A145325	②TR22607
Hose - Upper .....		≡<21115
Hose - Lower .....		●26536
Hose - By Pass .....		24220
<b>2294</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1987-1983		
Belt - Fan & Alt.; W/A.C. ....	A145325	②TR22607
Belt - Fan & Alt.; W/O A.C. ....	A57130	TR22607
Belt - Fan To A.C. ....	A9628	▲9447HD
Hose - Upper .....		≡<21115
Hose - Lower .....		●26536
Hose - By Pass .....		24220
<b>2390</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1983-1978		
Belt - A.C. ....	A9628	▲9447HD
Belt - Fan & Alt. ....	A145325	②TR22607
Hose - Upper .....		≡<21115
Hose - Lower .....		●26536
Hose - By Pass .....		24220
<b>2394</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1987-1983		
Belt - Fan & Alt.; W/A.C. ....	A145325	②TR22607
Belt - Fan & Alt.; W/O A.C. ....	A57130	TR22607
Belt - Fan To A.C. ....	A9628	▲9447HD
Hose - Upper .....		≡<21115
Hose - Lower .....		●26536
Hose - By Pass .....		24220
<b>2470</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1979-1971		
Belt - A.C.; W/44 1/4" Belt O.C. ....	A75577	▲9440HD
Belt - A.C.; W/45 3/4" Belt O.C. ....	A76758	▲9455HD
Belt - A.C.; W/48 1/4" Belt O.C. ....	A135265	▲9480HD
Belt - Fan & Alt. ....	A61048	TR22578
Hose - Upper .....		●26530
Hose - By Pass .....		24220
<b>2590</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1983-1978		
Belt - A.C. ....	A9628	▲9447HD
Belt - Fan & Alt. ....	A145325	②TR22607
Hose - Upper .....		≡<21115
Hose - Lower .....		●26536
Hose - By Pass .....		24220
<b>2594</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1987-1983		
Belt - A.C. ....	A9628	▲9447HD
Belt - Fan & Alt. ....	A145325	②TR22607
Hose - Upper .....		≡<21115
Hose - Lower .....		●26536
Hose - By Pass .....		24220

Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>2670</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1979-1974		
Belt - A.C. ....	A135265	▲9480HD
Belt - Fan & Alt. ....	A77082	②TR22625
Hose - Upper .....		●26529
<b>2870</b>		
<b>Scania 6-Cyl. 673 Diesel</b>		
1979-1976		
Belt - A.C. ....	A138760	▲9500HD
Belt - Fan & Alt. ....	A138001	②▲9620HD
Hose - Upper .....		●26522
Hose - Lower - Pipe To Rad. ....		24228
<b>3294</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1986-1983		
Belt - Fan & Alt.; W/A.C. ....	A145325	②TR22607
Belt - Fan & Alt.; W/O A.C. ....	A57130	TR22607
Belt - Fan To A.C. ....	A9628	▲9447HD
Hose - Upper .....		≡<21115
Hose - Lower .....		or ●26523
Hose - Lower .....		●26536
<b>4490</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1983-1979		
Belt - A.C. ....	A135265	▲9480HD
Belt - Fan & Alt. ....	A61048	②TR22578
Hose - Upper .....		●26530
<b>4494</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1987-1984		
Belt - A.C. ....	A135265	▲9480HD
Belt - Fan & Alt. ....	A61048	②TR22578
Hose - Upper; 90 Deg. Bend Hose .....		≡<21115
Hose - Upper; W/S-Shaped Hose .....		●26530
<b>4690</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1983-1979		
Belt - A.C. ....	A139265	▲9490HD
Belt - Fan & Alt. ....	A76745	②TR22607
<b>4694</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1987-1984		
Belt - Fan & Alt. ....	A76745	②TR22607
<b>4890</b>		
<b>Scania 6-Cyl. 673 Diesel</b>		
1983-1979		
Belt - A.C. ....	A138760	▲9500HD
Belt - Fan & Alt. ....	A138001	②▲9620HD
Hose - Upper .....		●26510
Hose - Lower - Eng. To Pipe .....		≡<20957
Hose - Lower - Pipe To Rad. ....		24228
<b>4894</b>		
<b>Scania 6-Cyl. 673 Diesel</b>		
1987-1984		
Belt - A.C. ....	A34820	②▲9490HD
Belt - Fan & Alt. ....	A138001	②▲9620HD
Hose - Upper .....		24224
Hose - Lower .....		or ●25487
Hose - Lower .....		24232
<b>4994</b>		
<b>Scania V-8 866 Diesel</b>		
1988-1984		
Belt - A.C. ....		▲9440HD

②Two Required ≡<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>4994 - Continued</b>		
<b>Scania V-8 866 Diesel - Continued</b>		
1988-1984 - Continued		
Belt - Fan To Alt. ....	L50593	▲9490HD
Hose - Upper .....		≡20731
		or ●26525
Hose - Lower - Eng. To Pipe .....		24240
Hose - Lower - Pipe To Rad. ....		●26531
<b>AE</b>		
<b>Case C</b>		
1929-1927		
Belt - Fan .....	02696AB1	TR30467
<b>D; DC</b>		
<b>Case 4-Cyl. 260</b>		
1953-1939		
Belt - Fan .....	02696AB1	TR30467
Belt - Gen. ....	08280AB	6926
Hose - Upper .....		24236
		or ●26519
Hose - Lower .....		24226
<b>DC3; DC4</b>		
<b>Case 4-Cyl. 260</b>		
1953-1939		
Belt - Fan .....	02696AB1	TR30467
Belt - Gen. ....	08280AB	6926
Hose - Upper .....		24236
		or ●26519
Hose - Lower .....		24226
<b>Case 4-Cyl. 260 Distillate</b>		
1953-1939		
Belt - Fan .....	02696AB1	TR30467
Belt - Gen. ....	08280AB	6926
Hose - Upper .....		24236
		or ●26519
Hose - Lower .....		24226
<b>DCS</b>		
<b>Case 4-Cyl. 260</b>		
1953-1939		
Belt - Fan .....	02696AB1	TR30467
Belt - Gen. ....	08280AB	6926
<b>Case 4-Cyl. 260 Distillate</b>		
1953-1939		
Belt - Fan .....	02696AB1	TR30467
Belt - Gen. ....	08280AB	6926
<b>DE; DH; DI; DIM; DO; DS; DV</b>		
<b>Case 4-Cyl. 260</b>		
1953-1939		
Belt - Fan .....	02696AB1	TR30467
Belt - Gen. ....	08280AB	6926
Hose - Upper .....		24236
		or ●26519
Hose - Lower .....		24226
<b>Case 4-Cyl. 260 Distillate</b>		
1953-1939		
Belt - Fan .....	02696AB1	TR30467
Belt - Gen. ....	08280AB	6926
Hose - Upper .....		24236
		or ●26519
Hose - Lower .....		24226
<b>FC16</b>		
<b>Case 4-Cyl. 382</b>		
1929-1927		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449

Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>K</b>		
<b>Case 4-Cyl. 382 Kerosene</b>		
1929-1927		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449
<b>K2</b>		
<b>Case 4-Cyl. 382</b>		
1929-1927		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449
<b>L</b>		
<b>Case 4-Cyl. 403</b>		
1940-1929		
Belt - Fan .....	02696AB1	TR30467
Hose - Upper .....		24236
Hose - Lower .....		24236
<b>Case 4-Cyl. 403 Distillate</b>		
1940-1929		
Belt - Fan .....	02696AB1	TR30467
Hose - Upper .....		24236
Hose - Lower .....		24236
<b>Case 4-Cyl. 403 Kerosene</b>		
1940-1929		
Belt - Fan .....	02696AB1	TR30467
Hose - Upper .....		24236
Hose - Lower .....		24236
<b>LA</b>		
<b>Case 4-Cyl. 403</b>		
1953-1941		
Belt - Fan .....	06077AB	TR34467
Belt - Gen. ....	06185AB	TR22299
<b>Case 4-Cyl. 403 Distillate</b>		
1953-1941		
Belt - Fan .....	06077AB	TR34467
Belt - Gen. ....	06185AB	TR22299
<b>Case 4-Cyl. 403 LPG</b>		
1953-1941		
Belt - Fan .....	06077AB	TR34467
Belt - Gen. ....	06185AB	TR22299
<b>LAE; LAH; LAI; LAIH; LAIMH</b>		
<b>Case 4-Cyl. 403</b>		
1953-1941		
Belt - Fan .....	06077AB	TR34467
Belt - Gen. ....	06185AB	TR22299
Hose - Upper .....		24236
Hose - Lower .....		24236
<b>Case 4-Cyl. 403 Distillate</b>		
1953-1941		
Belt - Fan .....	06077AB	TR34467
Belt - Gen. ....	06185AB	TR22299
Hose - Upper .....		24236
Hose - Lower .....		24236
<b>Case 4-Cyl. 403 LPG</b>		
1953-1941		
Belt - Fan .....	06077AB	TR34467
Belt - Gen. ....	06185AB	TR22299
Hose - Upper .....		24236
Hose - Lower .....		24236

≡Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>LE; LEM; LI</b>		
<b>Case 4-Cyl. 403</b>		
1940-1929		
Belt - Fan .....	02696AB1	TR30467
<b>Case 4-Cyl. 403 Distillate</b>		
1940-1929		
Belt - Fan .....	02696AB1	TR30467
<b>Case 4-Cyl. 403 Kerosene</b>		
1940-1929		
Belt - Fan .....	02696AB1	TR30467
<b>LM</b>		
<b>Case 4-Cyl. 403</b>		
1953-1941		
Belt - Fan .....	02696AB1	TR30467
<b>M; M2</b>		
<b>Case W106</b>		
1952		
Belt - Fan .....	03782AB1	TR24400
Belt - Fan & Gen. ....	VT2102	TR24438
<b>M3B</b>		
<b>Case FA162</b>		
1960-1958		
Belt - Fan & Gen. ....	11585	TR24465
<b>O</b>		
<b>Case W106</b>		
1952		
Belt - Fan .....	03782AB1	TR24400
Belt - Fan & Gen. ....	VT2102	TR24438
<b>R; RA; RC</b>		
<b>Waukesha 4-Cyl. 133</b>		
1940-1935		
Hose - Upper .....		24232
Hose - Lower .....		24228
<b>S; SC</b>		
<b>Case 4-Cyl. 153</b>		
1954-1941		
Belt - Fan .....	06343AB	TR24489
Belt - Fan & Gen. ....	06344AB	TR24438
Hose - Upper .....		24228
<b>Case 4-Cyl. 165</b>		
1954-1941		
Belt - Fan .....	06343AB	TR24489
Belt - Fan & Gen. ....	06344AB	TR24438
Hose - Upper .....		24228
<b>SC3; SC4</b>		
<b>Case 4-Cyl. 153</b>		
1954-1941		
Belt - Fan .....	06343AB	TR24489
Belt - Fan & Gen. ....	06344AB	TR24438
<b>Case 4-Cyl. 153 Distillate</b>		
1954-1941		
Belt - Fan .....	06343AB	TR24489
Belt - Fan & Gen. ....	06344AB	TR24438
<b>Case 4-Cyl. 165</b>		
1954-1941		
Belt - Fan .....	06343AB	TR24489
Belt - Fan & Gen. ....	06344AB	TR24438
<b>Case 4-Cyl. 165 Distillate</b>		
1954-1941		
Belt - Fan .....	06343AB	TR24489
Belt - Fan & Gen. ....	06344AB	TR24438

Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>SE</b>		
<b>Case S</b>		
1954-1941		
Belt - Fan .....	06343AB	TR24489
Belt - Fan & Gen. ....	06344AB	TR24438
Hose - Upper .....		24228
<b>SI; SO</b>		
<b>Case 4-Cyl. 153</b>		
1954-1941		
Belt - Fan .....	06343AB	TR24489
Belt - Fan & Gen. ....	06344AB	TR24438
Hose - Upper .....		24228
<b>Case 4-Cyl. 153 Distillate</b>		
1954-1941		
Belt - Fan .....	06343AB	TR24489
Belt - Fan & Gen. ....	06344AB	TR24438
Hose - Upper .....		24228
<b>Case 4-Cyl. 165</b>		
1954-1941		
Belt - Fan .....	06343AB	TR24489
Belt - Fan & Gen. ....	06344AB	TR24438
Hose - Upper .....		24228
<b>Case 4-Cyl. 165 Distillate</b>		
1954-1941		
Belt - Fan .....	06343AB	TR24489
Belt - Fan & Gen. ....	06344AB	TR24438
Hose - Upper .....		24228
<b>V</b>		
<b>Continental 4-Cyl. 124</b>		
1942-1940		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449
Hose - Upper .....		24228
Hose - Lower .....		②24224
<b>VA</b>		
<b>Case 4-Cyl. 124</b>		
1955-1942		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449
Hose - Upper .....		24228
Hose - Lower .....		②24224
<b>VAC</b>		
<b>Case 4-Cyl. 124 Distillate</b>		
1955-1942		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449
Hose - Upper .....		24228
Hose - Lower .....		②24224
<b>Continental 4-Cyl. 124</b>		
1955-1942		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449
Hose - Upper .....		24228
Hose - Lower .....		②24224
<b>VAE</b>		
<b>Case 4-Cyl. 124 Distillate</b>		
1955-1942		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449

②Two Required

Agricultural Equipment



Application	OEM No.	Our No.
<b>CASE - Continued</b>		
<b>VAE – Continued</b>		
<b>Continental 4–Cyl. 124</b>		
1955–1942		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449
<b>VAH; VAI; VAO</b>		
<b>Case 4–Cyl. 124 Distillate</b>		
1955–1942		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449
Hose - Upper .....		24228
Hose - Lower .....		②24224
<b>Continental 4–Cyl. 124</b>		
1955–1942		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449
Hose - Upper .....		24228
Hose - Lower .....		②24224
<b>VAS</b>		
<b>Case 4–Cyl. 124</b>		
1954–1951		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449
Hose - Upper .....		24228
Hose - Lower .....		②24224
<b>VC; VI; VO</b>		
<b>Continental 4–Cyl. 124</b>		
1942–1940		
Belt - Fan; W/O Gen. ....	03782AB	TR28406
Belt - Fan & Gen.; W/VT3467 Gen. ....	VT2102	TR24438
Belt - Fan & Gen.; W/VT4885 Gen. ....	VT4886	TR24449
Hose - Upper .....		24228
Hose - Lower .....		②24224
<b>CASE IH</b>		
<b>234</b>		
<b>Mitsubishi 3–Cyl. 52 Diesel</b>		
1986–1985		
Belt - Fan & Alt. ....	MD007528	7370
<b>235</b>		
<b>Mitsubishi 3–Cyl. 52 Diesel</b>		
1990–1986		
Belt - Fan & Alt. ....	MD007528	7370
<b>244</b>		
<b>Mitsubishi 3–Cyl. 60 Diesel</b>		
1986–1985		
Belt - Fan & Alt. ....	MD007528	7370
<b>245</b>		
<b>Mitsubishi 3–Cyl. 60 Diesel</b>		
1990–1986		
Belt - Fan & Alt. ....	MD007528	7370
Hose - Upper .....		≧20661
<b>254</b>		
<b>Mitsubishi 3–Cyl. 65 Diesel</b>		
1986–1985		
Belt - Fan & Alt. ....	MD007528	7370
Hose - Upper .....		●25251

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>255</b>		
<b>Mitsubishi 3–Cyl. 65 Diesel</b>		
1990–1986		
Belt - Fan & Alt. ....	MD007528	7370
Hose - Upper; W/1 1/4" I.D. Hose .....		≧20661
		or ●25250
Hose - Upper; W/1 1/8" I.D. Hose .....		●25150
<b>265</b>		
<b>Mitsubishi 3–Cyl. 79 Diesel</b>		
1991–1987		
Belt - Fan & Alt. ....	MB041704	7390
Hose - Upper; W/1 1/4" I.D. Hose .....		≧20661
		or ●25250
Hose - Upper; W/1 1/8" I.D. Hose .....		●25150
<b>274</b>		
<b>Nissan 3–Cyl. 99 Diesel</b>		
1988–1979		
Belt - Fan & Alt. ....	197810984	▲9390HD
Hose - Upper .....		●25474
<b>275</b>		
<b>Mitsubishi 3–Cyl. 91 Diesel</b>		
1991–1986		
Belt - Fan & Alt. ....	1962770C1	7385
<b>385</b>		
<b>Case IH 3–Cyl. 155 Diesel</b>		
1990–1985		
Belt - Fan & Alt. ....	131303C91	▲9600HD
<b>395</b>		
<b>Case IH 3–Cyl. 155 Diesel</b>		
1994–1991		
Belt - Fan & Alt. ....	131303C91	▲9600HD
<b>485</b>		
<b>Case 3–Cyl. 179 Diesel</b>		
1990–1985		
Belt - Fan & Alt. ....	131303C91	▲9600HD
<b>495</b>		
<b>Case 3–Cyl. 179 Diesel</b>		
1994–1991		
Belt - Fan & Alt. ....	3129140R1	▲9610HD
<b>585</b>		
<b>Case 4–Cyl. 206 Diesel</b>		
1990–1985		
Belt - Fan & Alt. ....	131303C91	▲9600HD
<b>595</b>		
<b>Case IH 4–Cyl. 206 Diesel</b>		
1994–1991		
Belt - Fan & Alt.; W/A.C. ....	1607227C1	▲9625HD
Belt - Fan & Alt.; W/O A.C. ....	3129140R1	▲9610HD
<b>685</b>		
<b>Case 4–Cyl. 239 Diesel</b>		
1990–1986		
Belt - Fan & Alt. ....	131303C91	▲9600HD
<b>695</b>		
<b>Case 4–Cyl. 239 Diesel</b>		
1994–1991		
Belt - Fan & Alt.; W/A.C. ....	1607227C1	▲9625HD
Belt - Fan & Alt.; W/O A.C. ....	3129140R1	▲9610HD

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>885</b>		
<b>Case 4-Cyl. 268 Diesel</b>		
1990-1986		
Belt - Fan & Alt. ....	3129140R1	▲9610HD
Hose - Upper .....		≈20957
	or	●26502
<b>895</b>		
<b>Case IH 4-Cyl. 268 Diesel</b>		
1994-1991		
Belt - Fan & Alt. ....		▲9625HD
<b>995</b>		
<b>Case 4-Cyl. 268 Diesel</b>		
1991		
Belt - Fan; W/62" Belt O.C. ....	3129139R1	▲9620HD
<b>1120</b>		
<b>Mitsubishi 3-Cyl. 65 Diesel</b>		
1991		
Belt - Fan & Alt. ....		7355
<b>1130</b>		
<b>Mitsubishi 3-Cyl. 75 Diesel</b>		
1991		
Belt - Fan & Alt. ....		7355
<b>1140</b>		
<b>Mitsubishi 3-Cyl. 91 Diesel</b>		
1991		
Belt - Fan & Alt. ....	MD027458	7375
<b>1394</b>		
<b>Case 4-Cyl. 219 Diesel</b>		
1990-1983		
Belt - Fan & Alt. ....		7460
Hose - Upper; Molded Hose .....		●25474
Hose - Upper; Strt. Hose .....		24224
<b>1494</b>		
<b>Case 4-Cyl. 219 Diesel</b>		
1990-1983		
Belt - A.C. ....	K307429	▲9400HD
Belt - Fan & Alt.; W/A.C. ....	K308448	▲9490HD
Belt - Fan & Alt.; W/O A.C. ....	K68073	7465
<b>1594</b>		
<b>Case 6-Cyl. 329 Diesel</b>		
1990-1983		
Belt - A.C. ....		▲9520HD
Belt - Fan .....		7508
Belt - W.P. & Alt. ....		7500
Hose - Upper .....		●25484
<b>1896; 2096</b>		
<b>Case 6-Cyl. 359 Diesel</b>		
1992-1985		
Belt - Fan & Alt.; W/62 1/2" Belt O.C. ....	J903099	▲K080620HD
Belt - Fan & Alt.; W/62 7/8" Belt O.C. ....	3902309	▲K080623HD
Belt - Fan To A.C. ....	A169970	▲9390HD
Hose - Upper .....		●26612
Hose - Lower; Molded Hose .....		●26521
Hose - Lower; Strt. Hose .....		24236
<b>3220</b>		
<b>Case 3-Cyl. 179 Diesel</b>		
1997-1994		
Belt - A.C. ....	84657C1	▲9670HD

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>3394</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1987-1985		
Belt - Fan & Alt. ....	A145325	②TR22607
Belt - Fan To A.C. ....	A9628	▲9447HD
Hose - Upper .....		≈21115
<b>3594</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1987-1985		
Belt - Fan & Alt.; W/A.C. ....	A145325	②TR22607
Belt - Fan & Alt.; W/O A.C. ....	A57130	TR22607
Belt - Fan To A.C. ....	A9628	▲9447HD
Hose - Upper .....		≈21115
Hose - Lower; Single I.D. Hose .....		●26536
Hose - By Pass .....		24220
<b>4210</b>		
<b>Case 4-Cyl. 239 Diesel</b>		
1997-1994		
Belt - Fan & A.C. ....	84657C1	▲9670HD
Belt - Fan & Alt. ....	3128140R1	▲9610HD
Hose - Upper .....		20046
	or	●26501
<b>4230</b>		
<b>Case 4-Cyl. 268 Diesel</b>		
1997-1994		
Belt - Fan & A.C. ....	84657C1	▲9670HD
Belt - Fan & Alt. ....	3128140R1	▲9610HD
Hose - Upper .....		20046
	or	●26501
<b>4240</b>		
<b>Case 4-Cyl. 268 Diesel</b>		
1997		
Belt - Fan & Alt. ....		▲9630HD
Hose - Upper .....	1536489C1	●26504
1996-1994		
Belt - Fan & Alt. ....		▲9630HD
Hose - Upper .....		●26504
<b>4494</b>		
<b>Case 6-Cyl. 504 Diesel</b>		
1988-1984		
Belt - A.C. ....	A135265	▲9480HD
Belt - Fan & Alt. ....	A61048	②TR22578
<b>4894</b>		
<b>Scania 6-Cyl. 674 Diesel</b>		
1988-1984		
Hose - Upper .....		24224
	or	●25487
Hose - Lower .....		24432
<b>4994</b>		
<b>Saab-Scania V-8 866 Diesel</b>		
1988-1984		
Hose - Upper .....		≈20731
	or	●26525
Hose - Lower - Eng. To Pipe .....		24440
Hose - Lower - Pipe To Rad. ....		●26531
<b>5120</b>		
<b>Case 4-Cyl. 239 Diesel</b>		
1992-1990		
Belt - A.C.; W/39 5/8" Belt O.C. ....	84766C1	▲9390HD
Belt - A.C.; W/40 3/8" Belt O.C. ....	A184652	▲9400HD
Belt - Fan & Alt.; W/58 1/8" Belt O.C. ....	J911562	▲K080575HD
Belt - Fan & Alt.; W/59 5/8" Belt O.C. ....	J911558	▲K080590HD
Hose - Upper .....		●26502
Hose - Lower .....		●26520

②Two Required ≈Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>5130; 5140</b>		
<b>Case 6-Cyl. 359 Diesel</b>		
1992-1990		
Belt - A.C.; W/39 5/8" Belt O.C. ....	84766C1	▲9390HD
Belt - A.C.; W/40 3/8" Belt O.C. ....	A184652	▲9400HD
Belt - Fan & Alt.; W/58 1/8" Belt O.C. ....	J911562	▲K080575HD
Belt - Fan & Alt.; W/59 5/8" Belt O.C. ....	J911558	▲K080590HD
Hose - Upper .....		●26502
Hose - Lower .....		●26520
<b>5220 Maxxum</b>		
<b>Case 4-Cyl. 239 Diesel</b>		
1997-1992		
Belt - A.C.; W/39 5/8" Belt O.C. ....	84766C1	▲9390HD
Belt - A.C.; W/40 3/8" Belt O.C. ....	A184652	▲9400HD
Belt - Fan & Alt.; W/58 1/8" Belt O.C. ....	J911562	▲K080575HD
Belt - Fan & Alt.; W/59 5/8" Belt O.C. ....	J911558	▲K080590HD
<b>5230 Maxxum; 5240 Maxxum</b>		
<b>Case 6-Cyl. 359 Diesel</b>		
1997-1992		
Belt - A.C.; W/39 5/8" Belt O.C. ....	84766C1	▲9390HD
Belt - A.C.; W/40 3/8" Belt O.C. ....	A184652	▲9400HD
Belt - Fan & Alt.; W/58 1/8" Belt O.C. ....	J911562	▲K080575HD
Belt - Fan & Alt.; W/59 5/8" Belt O.C. ....	J911558	▲K080590HD
Hose - Upper .....		●26611
Hose - Lower .....		●26520
<b>5250 Maxxum</b>		
<b>Case 6-Cyl. 359 Diesel</b>		
1997-1992		
Belt - A.C. ....	84766C1	▲9390HD
Belt - Alt. ....	J911562	▲K080575HD
Tensioner Assy. ....	J918944	38504
Hose - Upper .....		●26611
Hose - Lower .....		●26520
<b>7110 Magnum</b>		
<b>Case 6T830 Diesel</b>		
1993-1987		
Belt - A.C. ....	131403C1	▲9385HD
Belt - Fan, W.P. & Alt. ....	J911567	▲K080670HD
Tensioner Assy. - Fan, W.P. & Alt. ....	J918944	38504
Hose - Upper .....		●26523
Hose - Lower - Eng. To Pipe .....		21901
Hose - Lower - Pipe To Rad. ....		≧20756
<b>7120 Magnum</b>		
<b>Case 6T830 Diesel</b>		
1995-1987		
Belt - A.C. ....	131403C1	▲9385HD
Belt - Fan, W.P. & Alt. ....	J911567	▲K080670HD
Tensioner Assy. - Fan, W.P. & Alt. ....	J918944	38504
Hose - Upper .....		●26523
Hose - Lower - Eng. To Pipe .....		21901
Hose - Lower - Pipe To Rad. ....		≧20756
<b>7130 Magnum</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1995-1987		
Belt - A.C. ....	131403C1	▲9385HD
Belt - Fan & Alt. ....	J911567	▲K080670HD
Hose - Upper .....		●26523
Hose - Lower - Eng. To Pipe .....		21901
Hose - Lower - Pipe To Rad. ....		≧20756
<b>7140 Magnum</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1993-1987		
Belt - A.C. ....	131403C1	▲9385HD
Belt - Fan & Alt. ....	J911567	▲K080670HD
Hose - Upper .....		●26523
Hose - Lower - Eng. To Pipe .....		21901
Hose - Lower - Pipe To Rad. ....		≧20756

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>7150 Magnum</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1993-1990		
Belt - A.C. ....	131403C1	▲9385HD
Belt - Fan & Alt. ....	J911567	▲K080670HD
Hose - Upper .....		●26523
Hose - Lower - Eng. To Pipe .....		21901
Hose - Lower - Pipe To Rad. ....		≧20756
<b>7210 Magnum; 7220 Magnum</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1996-1993		
Belt - A.C. ....	131403C1	▲9385HD
Belt - Fan, W.P. & Alt. ....	J911567	▲K080670HD
Tensioner Assy. - Fan, W.P. & Alt. ....	J918944	38504
Hose - Lower - Eng. To Pipe .....		21901
Hose - Lower - Pipe To Rad. ....		≧20756
<b>7230 Magnum; 7240 Magnum; 7250 Magnum</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1996-1993		
Belt - A.C. ....	131403C1	▲9385HD
Belt - Fan & Alt. ....	J911567	▲K080670HD
Hose - Lower - Eng. To Pipe .....		21901
Hose - Lower - Pipe To Rad. ....		≧20756
<b>8910 Magnum; 8920 Magnum</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1999		
Belt - Fan & Alt. ....	J911567	▲K080670HD
Belt - Fan To A.C. ....	131403C1	▲9385HD
Tensioner Assy. - Fan & Alt. ....	J934817	38504
1998-1997		
Belt - Fan & Alt. ....	J911567	▲K080670HD
Belt - Fan To A.C. ....	131403C1	▲9385HD
<b>8930 Magnum</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1999-1997		
Belt - Fan To A.C. ....	131403C1	▲9385HD
Belt - Fan, W.P. & Alt. ....	J911567	▲K080670HD
Tensioner Assy. - Fan, W.P. & Alt. ....	J918944	38504
<b>8940 Magnum</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1999		
Belt - Fan & Alt. ....	J911567	▲K080670HD
Belt - Fan To A.C. ....	131403C1	▲9385HD
Tensioner Assy. - Fan & Alt. ....	J918944	38504
1998-1997		
Belt - Fan To A.C. ....	131403C1	▲9385HD
Belt - Fan, W.P. & Alt. ....	J911567	▲K080670HD
Tensioner Assy. - Fan, W.P. & Alt. ....	J918944	38504
<b>8950 Magnum</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1999		
Belt - Fan To A.C. ....	131403C1	▲9385HD
Belt - Fan, W.P. & Alt. ....	J911567	▲K080670HD
Tensioner Assy. - Fan & Alt. ....	J918944	38504
1998-1997		
Belt - Fan To A.C. ....	131403C1	▲9385HD
Belt - Fan, W.P. & Alt. ....	J911567	▲K080670HD
Tensioner Assy. - Fan, W.P. & Alt. ....	J918944	38504
<b>9110; 9130</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1990-1986		
Belt - A.C. ....	061451A	▲9520HD
Belt - Fan & Alt. ....	3905866	▲K080600HD
Hose - Upper .....		≧20731
Hose - Lower - Eng. To Pipe .....		≧20206

≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>9150</b>		
<b>Cummins 6-Cyl. 611 Diesel</b>		
1990-1986		
Belt - A.C. ....	016864	▲9390HD
Belt - Alt. ....	3037425	▲K050340HD
Belt - Fan ....	3034942	▲K080465HD
<b>9170; 9180</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1990-1986		
Belt - A.C. ....		▲9390HD
Belt - Alt. ....	3030103	▲9463HD
Belt - Fan; W/Serpentine Belt Drive ....		▲K080400HD
Belt - Fan; W/V-Belt Drive ....		②TR28445
Belt - W.P. ....		▲K060435HD
Hose - Upper; W/2 1/4" I.D. Hose ....		●26525
Hose - Upper; W/2" I.D. Hose ....		24232
	or	●26512
<b>9210</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1995-1990		
Belt - Alt. ....	J911557	▲K080560HD
<b>9230</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1995-1990		
Belt - Fan & Alt. ....	3905866	▲K080600HD
<b>9240</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1995-1990		
Belt - A.C. ....	061451A	▲9520HD
Belt - Fan & Alt. ....	J911572	▲K080610HD
Hose - Upper - Eng. To Pipe ....		②20731
Hose - Lower ....		21901
<b>9250</b>		
<b>Cummins 6-Cyl. 611 Diesel</b>		
1995-1990		
Belt - A.C.; W/40 7/8" Belt O.C. ....	907190T1	▲9405HD
Belt - A.C.; W/41 7/8" Belt O.C. ....	1250587C1	▲9415HD
Belt - Fan ....	3034943	▲K080505HD
Belt - W.P. To Alt. ....	3037425	▲K050340HD
Hose - Lower - Eng. To Pipe ....		●26533
Hose - Lower - Pipe To Rad. ....		24226
Hose - By Pass ....		24222
<b>9260</b>		
<b>Cummins 6-Cyl. 611 Diesel</b>		
1995-1990		
Belt - A.C.; W/40 7/8" Belt O.C. ....	907190T1	▲9405HD
Belt - A.C.; W/41 7/8" Belt O.C. ....	1250587C1	▲9415HD
Belt - Fan ....	3034943	▲K080505HD
Belt - W.P. To Alt. ....	3037425	▲K050340HD
<b>9270</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1995-1990		
Belt - A.C.; V-Belt; W/39 3/8" Belt O.C. ....		▲9390HD
Belt - A.C.; V-Belt; W/40 3/8" Belt O.C. ....	3040291	▲9400HD
Belt - A.C.; V-Belt; W/56 3/8" Belt O.C. ....	83695	▲9560HD
Belt - A.C.; W/Serpentine Belt Drive ....	217638	▲K060435HD
Belt - Alt. ....		②▲9463HD
Belt - Fan ....		②TR28454
Belt - W.P. ....		▲K060435HD
Hose - By Pass - Thermostat To Cyl. Head ....		②24216
Hose - By Pass - W.P. To Thermostat ....		24226
<b>9280</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1995-1990		
Belt - A.C.; V-Belt; W/39 3/8" Belt O.C. ....		▲9390HD
Belt - A.C.; V-Belt; W/40 3/8" Belt O.C. ....	3040291	▲9400HD

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>9280 - Continued</b>		
<b>Cummins 6-Cyl. 855 Diesel - Continued</b>		
1995-1990 - Continued		
Belt - A.C.; V-Belt; W/56 3/8" Belt O.C. ....	83695	▲9560HD
Belt - A.C.; W/Serpentine Belt Drive ....	217638	▲K060435HD
Belt - Alt. ....		②▲9463HD
Belt - Fan ....		②TR28454
Belt - W.P. ....		▲K060435HD
<b>9310 Steiger</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
1999-1996		
Belt - A.C. ....	907729T1	▲9530HD
Belt - Fan & Alt. ....	J911572	▲K080610HD
Tensioner Assy. - Fan & Alt. ....	J918944	38504
<b>9330 Steiger</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2000-1996		
Belt - A.C. ....	1250587C1	▲9415HD
Belt - Alt. ....	90-3650T1	▲K050340HD
<b>9350 Steiger</b>		
<b>Cummins M11 Diesel</b>		
2000-1996		
Belt - A.C. ....	1250587C1	▲9415HD
Belt - Fan & Alt. ....	3034943	▲K080505HD
Belt - W.P. To Alt. ....	903650T1	▲K050340HD
Hose - Lower ....	907298T2	●26533
Hose - By Pass ....		24226
<b>9370 Steiger</b>		
<b>Cummins N14 Diesel</b>		
2000-1996		
Belt - A.C. ....	907190T1	▲9405HD
Belt - Alt. ....	901375T1	②▲9463HD
Belt - Fan ....	178707	②TR28437
Belt - W.P. ....	902383T1	▲K060435HD
<b>9380 Steiger</b>		
<b>Cummins N14 Diesel</b>		
2000-1997		
Belt - A.C. ....	907190T1	▲9405HD
Belt - Alt. ....	901375T1	②▲9463HD
Belt - Fan ....	178707	②TR28437
Belt - W.P. ....	902383T1	▲K060435HD
1996		
Belt - A.C. ....	907190T1	▲9405HD
Belt - Alt. ....	901375T1	②▲9463HD
Belt - Fan ....	178707	②TR28437
Belt - W.P. ....	902383T1	▲K060435HD
Hose - Upper ....		●26524
<b>9390</b>		
<b>Cummins N14 Diesel</b>		
2000-1996		
Belt - A.C. ....	907190T1	▲9405HD
Belt - Alt. ....	908383T1	K050410
Belt - W.P. ....	902383T1	▲K060435HD
Hose - Upper ....		●26524
<b>C50; C60</b>		
<b>Case 3-Cyl. 165 Diesel</b>		
2002-1998		
Belt - W.P. ....	218509A1	②▲9550HD

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>C70</b>		
<b>Case 4-Cyl. 258 Diesel</b>		
2002-1998		
Belt - A.C. ....	228332A2	♣9355HD
<b>C80</b>		
<b>Case 4-Cyl. 244 Diesel</b>		
2002-1998		
Belt - A.C. ....	228332A2	♣9355HD
<b>C90</b>		
<b>Case 4-Cyl. 244 Diesel</b>		
2002-1998		
Belt - Fan & Alt. ....		Ⓣ7570
Belt - Fan To A.C. ....		♣9380HD
<b>C100</b>		
<b>Case 4-Cyl. 244 Diesel</b>		
2002-1997		
Belt - Fan & Alt. ....		Ⓣ7570
Belt - Fan To A.C. ....		♣9380HD
<b>CX50; CX60</b>		
<b>Case 3-Cyl. 165 Diesel</b>		
2002-1998		
Belt - A.C. ....	238215A3	♣9550HD
Belt - W.P. ....	218509A1	Ⓣ♣9550HD
<b>CX70</b>		
<b>Case 4-Cyl. 258 Diesel</b>		
2002-1998		
Belt - A.C.; W/35 1/2" Belt O.C. ....	228332A1	♣9355HD
Belt - W.P. ....	241895A2	Ⓣ7570
<b>CX80</b>		
<b>Case 4-Cyl. 244 Diesel</b>		
2002-1998		
Belt - A.C.; W/35 1/2" Belt O.C. ....	228332A1	♣9355HD
Belt - Alt.; W/57" Belt O.C. ....	241895A2	Ⓣ7570
Belt - W.P. ....	241895A2	Ⓣ7570
<b>CX90</b>		
<b>Case 4-Cyl. 244 Diesel</b>		
2002-1998		
Belt - Alt.; W/57" Belt O.C. ....	241895A2	Ⓣ7570
Belt - Fan & Alt. ....	241895A2	Ⓣ7570
Belt - Fan To A.C.; W/35 1/2" Belt O.C. ....	228332A1	♣9355HD
Belt - Fan To A.C.; W/38" Belt O.C. ....		♣9380HD
Belt - W.P. ....	241895A2	Ⓣ7570
<b>CX100</b>		
<b>Case 4-Cyl. 244 Diesel</b>		
2002-1998		
Belt - Fan & Alt. ....	241895A2	Ⓣ7570
Belt - Fan To A.C.; W/33 1/2" Belt O.C. ....	228332A1	♣9355HD
Belt - Fan To A.C.; W/38" Belt O.C. ....		♣9380HD
<b>D25; D29</b>		
<b>Shibaura 3-Cyl. 81 Diesel</b>		
2003-2001		
Belt - Fan & Alt. ....	86517954	AX36
<b>D33</b>		
<b>Shibaura 3-Cyl. 91 Diesel</b>		
2003-2001		
Belt - Fan & Alt. ....	86517954	AX36

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>D35</b>		
<b>Shibaura 3-Cyl. 101 Diesel</b>		
2006-2001		
Belt - Fan & Alt. ....	301525A1	♣9370HD
<b>D40</b>		
<b>Shibaura 4-Cyl. 121 Diesel</b>		
2006-2001		
Belt - Fan & Alt. ....	301525A1	♣9370HD
<b>D45</b>		
<b>Shibaura 4-Cyl. 135 Diesel</b>		
2004-2001		
Belt - Fan & Alt. ....	301525A1	♣9370HD
<b>DX25</b>		
<b>Shibaura 3-Cyl. 81 Diesel</b>		
2003-2002		
Belt - Fan & Alt. ....	86517954	AX36
<b>DX29</b>		
<b>Shibaura 3-Cyl. 81 Diesel</b>		
2006-2002		
Belt - Fan & Alt. ....	86517954	AX36
<b>DX33</b>		
<b>Shibaura 3-Cyl. 91 Diesel</b>		
2006-2002		
Belt - Fan ....	86517954	AX36
<b>DX35</b>		
<b>Shibaura 3-Cyl. 101 Diesel</b>		
2008-2002		
Belt - Fan & Alt. ....	301525A1	♣9370HD
<b>DX40</b>		
<b>Shibaura 4-Cyl. 121 Diesel</b>		
2008-2002		
Belt - Fan ....	301525A1	♣9370HD
<b>DX45</b>		
<b>Shibaura 4-Cyl. 135 Diesel</b>		
2008-2002		
Belt - Fan ....	301525A1	♣9370HD
<b>DX48; DX55</b>		
<b>Shibaura 4-Cyl. 135 Diesel</b>		
2007-2004		
Belt - Fan ....	86517954	AX36
<b>Farmall 31</b>		
<b>Case IH 3-Cyl. 91 Diesel</b>		
2012-2008		
Belt - Fan & Alt. ....	86517954	♣9370HD
<b>Farmall 35</b>		
<b>Case IH 3-Cyl. 101 Diesel</b>		
2012-2008		
Belt - Fan & Alt. ....	86517954	♣9370HD
<b>Farmall 40</b>		
<b>Case IH 4-Cyl. 121 Diesel</b>		
2012-2010		
Belt - A.C. ....	86401123	♣9470HD
Belt - Fan & Alt. ....	301525A1	♣9370HD
2009		
Belt - A.C. ....	86401123	♣9470HD
Belt - Alt. & W.P. ....	301525A1	♣9370HD
Belt - Fan & Alt. ....	301525A1	♣9370HD

ⓉTwo Required ♣Standard Belt May Also Be Available

**TRACTORS**



Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>Farmall 40 – Continued</b>		
<b>Case IH 4-Cyl. 121 Diesel – Continued</b>		
2008		
Belt - A.C. ....	86401123	♣9470HD
Belt - Fan & Alt. ....	301525A1	♣9370HD
<b>Farmall 45</b>		
<b>Case IH 4-Cyl. 135 Diesel</b>		
2012-2008		
Belt - A.C. ....	86401123	♣9470HD
Belt - Alt. & W.P. ....	301525A1	♣9370HD
<b>Farmall 45A</b>		
<b>Case IH 4-Cyl. 135 Diesel</b>		
2011-2010		
Belt - Fan ....	301525A1	♣9370HD
<b>Shibaura 4-Cyl. 135 Diesel</b>		
2013-2012		
Belt - Fan ....	301525A1	♣9370HD
<b>Farmall 50</b>		
<b>Case IH 4-Cyl. 135 Diesel</b>		
2012-2008		
Belt - A.C. ....	86401123	♣9470HD
Belt - Alt. & W.P. ....	301525A1	♣9370HD
<b>Farmall 55</b>		
<b>Case IH 4-Cyl. 135 Diesel</b>		
2012-2010		
Belt - A.C. ....	86401123	♣9470HD
Belt - Fan ....	301525A1	♣9370HD
2009		
Belt - A.C. ....	86401123	♣9470HD
Belt - Alt. & W.P. ....	86517954	♣9370HD
Belt - Fan ....	301525A1	♣9370HD
2008		
Belt - A.C. ....	86401123	♣9470HD
Belt - Fan ....	301525A1	♣9370HD
<b>Farmall 55A</b>		
<b>Case IH 4-Cyl. 135 Diesel</b>		
2011-2010		
Belt - Fan ....	301525A1	♣9370HD
<b>Shibaura 4-Cyl. 135 Diesel</b>		
2013-2012		
Belt - Fan ....	301525A1	♣9370HD
<b>Farmall 60</b>		
<b>Case IH 4-Cyl. 135 Diesel</b>		
2012-2008		
Belt - Fan ....	47131754	♣K080545HD
<b>Farmall 65C</b>		
<b>Case IH 4-Cyl. 195 Diesel</b>		
2013-2010		
Belt - Fan ....	87705737	♣K080550HD
2009		
Belt - Serpentine ....	87705737	♣K080550HD
Belt - Fan ....	87705737	♣K080550HD
2008		
Belt - Fan ....	87705737	♣K080550HD

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>Farmall 70</b>		
<b>Case IH 4-Cyl. 195 Diesel</b>		
2012-2009		
Belt - Fan ....	47131754	♣K080545HD
<b>Farmall 75A</b>		
<b>Case IH 4-Cyl. 195 Diesel</b>		
2013-2010		
Belt - Fan ....	87705737	♣K080550HD
<b>Farmall 75C</b>		
<b>Case IH 4-Cyl. 195 Diesel</b>		
2013-2010		
Belt - Fan ....	87705737	♣K080550HD
2009		
Belt - Serpentine ....	87705737	♣K080550HD
2008		
Belt - Fan ....	87705737	♣K080550HD
<b>Case IH 4-Cyl. 207 Diesel</b>		
2014		
Belt - Fan ....	87705737	♣K080550HD
<b>Farmall 75N</b>		
<b>Case IH 4-Cyl. 195 Diesel</b>		
2012-2009		
Belt - A.C. ....	87399981	K040358
Belt - Fan ....	87705737	♣K080550HD
<b>Farmall 80</b>		
<b>Case IH 4-Cyl. 195 Diesel</b>		
2012-2009		
Belt - Fan ....	87705737	♣K080550HD
<b>Farmall 85C</b>		
<b>Case IH 4-Cyl. 207 Diesel</b>		
2013		
Belt - Fan ....	47131754	♣K080545HD
<b>Case IH 4-Cyl. 274 Diesel</b>		
2012-2010		
Belt - Fan ....	47131754	♣K080545HD
2009		
Belt - Serpentine ....	47131754	♣K080545HD
2008		
Belt - Fan ....	47131754	♣K080545HD
<b>Farmall 85U; Farmall 90</b>		
<b>Case IH 4-Cyl. 274 Diesel</b>		
2012-2008		
Belt - Fan ....	47131754	♣K080545HD
<b>Farmall 95</b>		
<b>Case IH 4-Cyl. 274 Diesel</b>		
2012-2010		
Belt - Fan ....	47131754	♣K080545HD
2009		
Belt - Serpentine ....	47131754	♣K080545HD
2008		
Belt - Fan ....	47131754	♣K080545HD
<b>Farmall 95C</b>		
<b>Case IH 4-Cyl. 207 Diesel</b>		
2013		
Belt - Fan ....	47131754	♣K080545HD
<b>Case IH 4-Cyl. 274 Diesel</b>		
2012-2008		
Belt - Fan ....	47131754	♣K080545HD

♣Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>Farmall 95N</b>		
<b>Case IH 4-Cyl. 274 Diesel</b>		
2012-2009		
Belt - A.C. ....	87399981	K040358
Belt - Fan & Alt.; W/O Viscous Fan .....	47131754	▲K080545HD
Belt - Fan & Alt.; W/Viscous Fan .....	47135840	▲K080537HD
<b>Farmall 95U</b>		
<b>Case IH 4-Cyl. 274 Diesel</b>		
2012-2008		
Belt - Fan .....	47131754	▲K080545HD
<b>Farmall 105U</b>		
<b>Case IH 4-Cyl. 207 Diesel</b>		
2017-2013		
Belt - Fan; W/Viscous Fan .....	47131754	▲K080545HD
<b>Case IH 4-Cyl. 274 Diesel</b>		
2012-2008		
Belt - Fan; W/Viscous Fan .....	47131754	▲K080545HD
<b>Farmall 110A</b>		
<b>Case IH 4-Cyl. 274 Diesel</b>		
2017-2012		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan .....	4899178	▲K080610HD
Tensioner Assy. ....	2855622	38639
<b>Farmall 125A; Farmall 140A</b>		
<b>Case IH 6-Cyl. 411 Diesel</b>		
2013-2012		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan .....	4899178	▲K080610HD
Tensioner Assy. ....	2855622	38639
<b>FLX4010</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2006-2003		
Belt - A.C. ....	131403C1	▲9385HD
Belt - Fan & Alt. ....	3944840	▲K080774HD
<b>JX55</b>		
<b>Case 3-Cyl. 165 Diesel</b>		
2005-2002		
Belt - A.C. ....	5140009	7405
Belt - Alt. ....	4796327	7450
Belt - Fan .....	5094418	7410
<b>JX65</b>		
<b>Case 3-Cyl. 179 Diesel</b>		
2006-2002		
Belt - A.C. ....	5140009	7405
Belt - Alt. ....	4796327	7450
Belt - Fan .....	5094418	7410
<b>JX70</b>		
<b>Case 3-Cyl. 179 Diesel</b>		
2008-2006		
Belt - A.C. ....	5140009	7405
Belt - Fan .....	98473706	7453
<b>JX75</b>		
<b>Case 4-Cyl. 220 Diesel</b>		
2006		
Belt - A.C. ....	10AV1025	7405
Belt - Alt. ....	4796327	7450
Belt - Fan .....	5094418	7410
2005-2002		
Belt - A.C. ....	5140009	7405
Belt - Alt. ....	4796327	7450
Belt - Fan .....	5094418	7410

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>JX80U</b>		
<b>Case 4-Cyl. 238 Diesel</b>		
2004-2002		
Belt - A.C. ....	5140009	7405
Belt - Alt. ....	4796327	7450
Belt - Fan .....	5140010	7425
Hose - Lower - Eng. To Pipe .....	596152	24224
Hose - Lower - Rad. To Pipe .....	596152	24224
<b>JX85</b>		
<b>Case 4-Cyl. 238 Diesel</b>		
2006-2002		
Belt - A.C. ....	5140009	7405
Belt - Alt. ....	4796327	7450
Belt - Fan .....	5094418	7410
<b>JX90U</b>		
<b>Case 4-Cyl. 238 Diesel</b>		
2004-2002		
Belt - Alt. ....	4796327	7450
Belt - Fan .....	5140010	7425
Hose - Lower - Eng. To Pipe .....	596152	24224
Hose - Lower - Rad. To Pipe .....	596152	24224
<b>JX95</b>		
<b>Case 4-Cyl. 238 Diesel</b>		
2008-2002		
Belt - A.C. ....	5140009	7405
Belt - Alt. ....	4796327	7450
Belt - Fan .....	5094418	7410
<b>JX100U</b>		
<b>Case 4-Cyl. 238 Diesel</b>		
2004-2002		
Belt - Alt. ....	4796327	7450
Belt - Fan .....	5140010	7425
Hose - Lower .....	596152	24224
<b>JX1060C; JX1070C</b>		
<b>Case 3-Cyl. 179 Diesel</b>		
2008-2004		
Belt - A.C. ....	5154152	▲9345HD
Hose - Lower .....	596152	②24224
<b>JX1075C</b>		
<b>Case 3-Cyl. 179 Diesel</b>		
2008-2005		
Hose - Lower .....	596152	②24224
2004		
Belt - A.C. ....	5154152	▲9345HD
Hose - Lower .....	596152	②24224
<b>JX1075N</b>		
<b>Case 3-Cyl. 179 Diesel</b>		
2008-2004		
Hose - Lower .....	596152	②24224
<b>JX1080U</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2008-2004		
Belt - A.C. ....	47129821	▲9412HD
Belt - Fan & Alt. ....	47131754	▲K080545HD
<b>JX1085C</b>		
<b>Case 4-Cyl. 274 Diesel</b>		
2008-2006		
Belt - A.C. ....	47129821	▲9412HD
Belt - Fan & Alt. ....	47131754	▲K080545HD

②Two Required ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>JX1090U</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2008-2004		
Belt - A.C. ....	47129821	▲9412HD
Belt - Fan & Alt. ....	47131754	▲K080545HD
<b>JX1095C</b>		
<b>Case 4-Cyl. 274 Diesel</b>		
2008-2006		
Belt - A.C. ....	47129821	▲9412HD
Belt - Fan & Alt. ....	47131754	▲K080545HD
<b>JX1095N</b>		
<b>Case 4-Cyl. 238 Diesel</b>		
2008-2005		
Hose - Lower .....	596152	24224
<b>JX1100U</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2007-2004		
Belt - A.C. ....	47129821	▲9412HD
Belt - Fan & Alt.; W/O Viscous Fan .....	47131754	▲K080545HD
Belt - Fan & Alt.; W/Viscous Fan .....	47135840	▲K080537HD
<b>Magnum 180</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014-2011		
Belt - Fan .....	4899178	▲K080610HD
<b>Case 6-Cyl. 415 Diesel</b>		
2010-2009		
Belt - Fan .....	4899178	▲K080610HD
<b>Magnum 190</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2013-2010		
Belt - Fan .....	4899178	▲K080610HD
<b>Case 6-Cyl. 415 Diesel</b>		
2009		
Belt - Fan .....	4899178	▲K080610HD
<b>Magnum 200</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014		
Belt - Fan .....	4899178	▲K080610HD
<b>Magnum 210</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2013-2010		
Belt - Fan .....	4899178	▲K080610HD
<b>Case 6-Cyl. 415 Diesel</b>		
2009		
Belt - Fan .....	4899178	▲K080610HD
<b>Magnum 220</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014		
Belt - Fan .....	4899178	▲K080610HD
<b>Magnum 225</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014-2010		
Belt - Fan .....	4899178	▲K080610HD
<b>Magnum 240</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014		
Belt - Fan .....	4899178	▲K080610HD

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>Maxxum 110</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2014-2007		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	▲K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	▲K080605HD
<b>Maxxum 110 Limited</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2010		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	▲K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	▲K080605HD
<b>Maxxum 110 Pro</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2011-2007		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	▲K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	▲K080605HD
<b>Maxxum 115</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014-2007		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	▲K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	▲K080605HD
<b>Maxxum 115 Limited</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2010		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	▲K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	▲K080605HD
<b>Maxxum 120</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2014		
Belt - Alt. ....	4899178	▲K080610HD
2013-2012		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	▲K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	▲K080605HD
<b>Maxxum 120 Pro</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2011-2009		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	▲K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	▲K080605HD
2008		
Belt - A.C. ....	87802911	K040390
Belt - Fan; Ser. No. C6358 & Before .....	4899178	▲K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	▲K080605HD
2007		
Belt - A.C. ....	87802911	K040390
Belt - Fan; Ser. No. C6358 & Before .....	4899178	▲K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	▲K080605HD
Belt - Fan & Alt. ....	4899178	▲K080610HD
<b>Maxxum 125</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014-2007		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	▲K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	▲K080605HD
<b>Maxxum 125 Limited</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2010		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	▲K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	▲K080605HD

▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>Maxxum 125 Pro</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2011-2007		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	♣K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	♣K080605HD
<b>Maxxum 130</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2014		
Belt - Alt. ....	4899178	♣K080610HD
2013-2012		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	♣K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	♣K080605HD
<b>Maxxum 130 Pro</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2011-2007		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	♣K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	♣K080605HD
<b>Maxxum 140</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014-2012		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	♣K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	♣K080605HD
<b>Maxxum 140 Limited</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2010		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	♣K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	♣K080605HD
<b>Maxxum 140 Pro</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2011-2007		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. C6358 & Before .....	4899178	♣K080610HD
Belt - Fan; Ser. No. D6358 & After .....	2858019	♣K080605HD
<b>MX80C; MX90C</b>		
<b>Case 4-Cyl. 244 Diesel</b>		
2002-1998		
Belt - Fan & Alt. ....	241895A2	Ⓣ7570
Belt - Fan To A.C. ....		Ⓣ♣9385HD
<b>MX100</b>		
<b>Case 6-Cyl. 359 Diesel</b>		
2002-1996		
Belt - Fan To A.C. ....	A184652	♣9400HD
Belt - Fan, W.P. & Alt. ....	J911558	♣K080590HD
Tensioner Assy. - Fan, W.P. & Alt. ....	J918944	38504
<b>MX100C</b>		
<b>Case 4-Cyl. 244 Diesel</b>		
2001-1998		
Belt - Fan & Alt. ....	241895A2	Ⓣ7570
Belt - Fan To A.C. ....		Ⓣ♣9385HD
<b>MX110; MX120; MX135</b>		
<b>Case 6-Cyl. 359 Diesel</b>		
2002-1996		
Belt - Fan To A.C. ....	A184652	♣9400HD
Belt - Fan, W.P. & Alt.; W/57 1/2" Belt O.C. .	J911562	♣K080575HD
Belt - Fan, W.P. & Alt.; W/59" Belt O.C. ....	J911558	♣K080590HD
Tensioner Assy. - Fan, W.P. & Alt. ....	J918944	38504

ⓉTwo Required ♣Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>MX150</b>		
<b>Case 6-Cyl. 359 Diesel</b>		
2002-1998		
Belt - Fan To A.C. ....	84766C1	♣9390HD
Belt - Fan, W.P. & Alt.; W/57 1/2" Belt O.C. .	J911562	♣K080575HD
Belt - Fan, W.P. & Alt.; W/59" Belt O.C. ....	J911558	♣K080590HD
Tensioner Assy. - Fan, W.P. & Alt. ....	J936203	38504
1997		
Belt - Fan To A.C. ....	84766C1	♣9390HD
Belt - Fan, W.P. & Alt.; W/57 1/2" Belt O.C. .	J911562	♣K080575HD
Belt - Fan, W.P. & Alt.; W/59" Belt O.C. ....	J911558	♣K080590HD
<b>MX170</b>		
<b>Case 6-Cyl. 359 Diesel</b>		
2002-1997		
Belt - Fan To A.C. ....	84766C1	♣9390HD
Belt - Fan, W.P. & Alt.; W/57 1/2" Belt O.C. .	J911562	♣K080575HD
Belt - Fan, W.P. & Alt.; W/59" Belt O.C. ....	J911558	♣K080590HD
Tensioner Assy. - Fan, W.P. & Alt. ....	J936203	38504
<b>MX180; MX200</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2002-1999		
Belt - A.C. ....	A189040	♣9463HD
Belt - Air Brake Compr. ....	A189040	♣9463HD
Tensioner Assy. ....	J936203	38504
1998		
Belt - A.C. ....	A189040	♣9463HD
Belt - Compr. ....	A189040	♣9463HD
Tensioner Assy. ....	J936203	38504
<b>MX210</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2006-2001		
Belt - Fan, W.P. & Alt. ....	87402830	♣K080820HD
Tensioner Assy. ....	87409564	38516
<b>MX220</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2002-2000		
Belt - A.C. ....	A189040	♣9463HD
Belt - Air Brake Compr. ....	A189040	♣9463HD
Tensioner Assy. ....	J936203	38504
1999-1998		
Belt - A.C. ....	A189040	♣9463HD
Belt - Compr. ....	A189040	♣9463HD
Tensioner Assy. ....	J936203	38504
<b>MX230</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2006-2001		
Belt - Fan, W.P. & Alt. ....	87402830	♣K080820HD
Tensioner Assy. ....	87409564	38516
<b>MX240</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2002-1998		
Belt - Fan & Alt. ....	243373A1	♣K080675HD
Belt - Fan To A.C. ....	A189040	♣9463HD
Tensioner Assy. ....	J945849	38516
<b>MX255</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2006-2001		
Belt - Fan, W.P. & Alt. ....	87402831	♣K080816HD
Tensioner Assy. ....	87409564	38516
<b>MX270</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2002-1998		
Belt - Fan & Alt. ....	243373A1	♣K080675HD
Belt - Fan To A.C. ....	A189040	♣9463HD
Tensioner Assy. ....	J945849	38516

Agricultural Equipment



Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>MX285</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2006-2001		
Belt - Fan, W.P. & Alt. ....	87402831	▲K080816HD
Tensioner Assy. ....	87409564	38516
<b>MXM120; MXM130; MXM140; MXM155; MXM175; MXM190</b>		
<b>Case 6-Cyl. 456 Diesel</b>		
2007-2002		
Belt - Fan .....	87802822	▲K080806HD
<b>MXU100</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2006-2005		
Belt - A.C. ....	87802911	K040390
Belt - Fan .....		▲K080610HD
Belt - Fan & Alt. ....	4899178	▲K080610HD
Belt - W.P. ....	4899178	▲K080610HD
2004		
Belt - A.C. ....	87802911	K040390
Belt - Fan .....		▲K080610HD
Belt - Fan & Alt. ....	4899178	▲K080610HD
<b>MXU110</b>		
<b>Case 4-Cyl. 273 Diesel</b>		
2006-2004		
Belt - A.C. ....	87802911	K040390
Belt - W.P. ....	4899178	▲K080610HD
<b>MXU125</b>		
<b>Case 6-Cyl. 410 Diesel</b>		
2006-2004		
Belt - A.C. ....	87802911	K040390
Belt - Fan To Alt. ....	4899178	▲K080610HD
<b>MXU135</b>		
<b>Case 6-Cyl. 410 Diesel</b>		
2006-2004		
Belt - A.C. ....	87802911	K040390
Belt - W.P. ....	4899178	▲K080610HD
<b>Puma 125</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2012		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan & W.P. ....	4899178	▲K080610HD
2010-2008		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan & W.P. ....	4899178	▲K080610HD
<b>Puma 130</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014-2010		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan & W.P. ....	4899178	▲K080610HD
<b>Puma 140</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2010-2008		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan & W.P. ....	4899178	▲K080610HD
<b>Puma 145</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014-2010		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan & W.P. ....	4899178	▲K080610HD

Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>Puma 150</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014		
Belt - Fan .....	243373A1	▲K080675HD
<b>Puma 155</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2011-2008		
Belt - Fan & W.P. ....	84229205	▲K080675HD
<b>Puma 160</b>		
<b>Case 6-Cyl. 411 Diesel</b>		
2014-2010		
Belt - A.C. ....	87710661	▲K040388HD
Belt - Fan & W.P. ....	84229205	▲K080675HD
<b>Steiger 435</b>		
<b>Case 6-Cyl. 787 Diesel</b>		
2009-2007		
Belt - Fan .....	87282333	▲K080991HD
<b>STX275</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2006-2000		
Belt - Hub & A.C. ....	A189040	▲9463HD
Belt - W.P. & Alt.; Ser. No. JEE0099500 & Before .....	3911567	▲K080670HD
Tensioner Assy. - Alt. & W.P.; Ser. No. JEE0099500 & Before .....	J945849	38516
Tensioner Assy. - Alt. & W.P.; Ser. No. JEE0099501 & After .....	87326910	38504
<b>STX280</b>		
<b>Case 6-Cyl. 505 Diesel</b>		
2007-2006		
Belt - A.C. ....	A189040	▲9463HD
Belt - Alt. & A.C. ....	87437226	▲K060625HD
Tensioner Assy. - Alt. & A.C. ....	J936213	38516
Tensioner Pulley - Alt. & A.C. ....	J936213	36093
<b>STX325</b>		
<b>Case 6-Cyl. 543 Diesel</b>		
2006-2000		
Belt - A.C. ....	A189040	▲9463HD
Belt - W.P. & Alt. ....	3911567	▲K080670HD
<b>STX330</b>		
<b>Case 6-Cyl. 543 Diesel</b>		
2007-2006		
Belt - A.C. ....	A189040	▲9463HD
Belt - Alt. ....	87437226	▲K060625HD
Tensioner Assy. - Alt. ....	J936213	38516
Tensioner Pulley .....	J936213	36093
<b>STX375</b>		
<b>Cummins 6-Cyl. 912 Diesel</b>		
2006-2003		
Belt - Alt. & A.C. ....	87437226	▲K060625HD
Belt - W.P. ....	325289A1	▲K120400HD
2002		
Belt - Alt. & A.C. ....	87437226	▲K060625HD
2001-2000		
Belt - Alt. & A.C. ....	87437226	▲K060625HD
Belt - W.P. ....	325289A1	▲K120400HD
<b>STX380</b>		
<b>Case 6-Cyl. 787 Diesel</b>		
2007-2006		
Belt - Fan & Alt. ....	504078066	▲K080991HD
Belt - Fan, Alt. & A.C. ....	87437226	▲K060625HD

▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>CASE IH - Continued</b>		
<b>STX425</b>		
<b>Cummins 6-Cyl. 912 Diesel</b>		
2006-2001		
Belt - Alt. & A.C. ....	87437226	♣K060625HD
Belt - W.P. ....	325289A1	♣K120400HD
<b>STX430</b>		
<b>Case 6-Cyl. 787 Diesel</b>		
2007-2006		
Belt - Alt. & A.C. ....	87437226	♣K060625HD
Belt - W.P. ....	504078066	♣K080991HD
<b>STX440</b>		
<b>Cummins 6-Cyl. 912 Diesel</b>		
2002-2000		
Belt - Alt. ....	325290A1	♣K060625HD
Belt - W.P. ....	325289A1	♣K120400HD
<b>STX450</b>		
<b>Cummins 6-Cyl. 912 Diesel</b>		
2006-2003		
Belt - Alt. & A.C. ....	87437226	♣K060625HD
Belt - W.P. ....	325289A1	♣K120400HD
2002		
Belt - Alt. & A.C. ....	87437226	♣K060625HD
Belt - W.P. ....	325289A1	♣K120400HD
Tensioner Assy. - Fan .....	3100118	38620
2001		
Belt - Alt. & A.C. ....	87437226	♣K060625HD
Belt - W.P. ....	325289A1	♣K120400HD
<b>STX480</b>		
<b>Cummins 6-Cyl. 915 Diesel</b>		
2007-2006		
Belt - Alt. & A.C. ....	87437226	♣K060625HD
Belt - W.P. ....	325289A1	♣K120400HD
<b>STX500</b>		
<b>Cummins 6-Cyl. 912 Diesel</b>		
2006-2004		
Belt - Alt. & A.C. ....	87437226	♣K060625HD
Belt - W.P. ....	325289A1	♣K120400HD
<b>STX530</b>		
<b>Cummins 6-Cyl. 915 Diesel</b>		
2007-2006		
Belt - Alt. & A.C. ....	87437226	♣K060625HD
Belt - W.P. ....	325289A1	♣K120400HD
<b>CATERPILLAR</b>		
<b>561B (62A)</b>		
<b>Caterpillar D333 Diesel</b>		
1967-1959		
Belt - Gen.; W/69 1/4" Belt O.C. ....	7M5972	②TR24688
Belt - Gen.; W/71 1/8" Belt O.C. ....	5M6096	②TR24709
Belt - Starter; Ser. No. 62A1 Thru 62A191 ..	5M6096	②TR24709
Belt - W.P. ....	4M9386	②TR24709
<b>561C (85H)</b>		
<b>Caterpillar D333 Diesel</b>		
1967-1966		
Belt - Gen. ....	5M6096	②TR24709
<b>571E PS (64A)</b>		
<b>Caterpillar D333 Diesel</b>		
1972-1961		
Belt - Alt. ....	2S9778	♣9590HD
Belt - Fan; Ser. No. 64A1 Thru 64A151;		
W/81 1/8" Belt O.C. ....	3L6052	②TR30808
Belt - Fan; Ser. No. 64A1 Thru 64A151;		
W/85 5/8" Belt O.C. ....	5H7371	②CX81
Belt - Gen.; Ser. No. 64A152 Thru 64A221 .	3S6272	♣9530HD

Application	OEM No.	Our No.
<b>CATERPILLAR - Continued</b>		
<b>571E PS (64A) - Continued</b>		
<b>Caterpillar D333 Diesel - Continued</b>		
1972-1961 - Continued		
Belt - Gen.; Ser. No. 64A222 & After .....	2S5218	♣9580HD
<b>571F (95N)</b>		
<b>Caterpillar D333 Diesel</b>		
1974-1972		
Belt - Fan .....	3L6052	②TR30808
<b>571G (16W)</b>		
<b>Caterpillar D3306 Diesel</b>		
1985-1976		
Belt - Fan & Alt. ....		②CX81
Hose - Upper .....		24446
Hose - Lower .....		24440
<b>572C (21A)</b>		
<b>Caterpillar D399 Diesel</b>		
1961-1957		
Belt - Fan; Ser. No. 21A270 Thru 21A331 ...	2M8183	TR30672
<b>572D (21A)</b>		
<b>Caterpillar D339 Diesel</b>		
1961-1959		
Belt - Fan; Ser. No. 21A270 Thru 21A331 ...	2M8183	TR30672
<b>572E (65A)</b>		
<b>Caterpillar D399T Diesel</b>		
1972-1961		
Belt - Alt. ....	2S9778	♣9590HD
Belt - Fan; W/81 1/8" Belt O.C. ....	3L6052	②TR30808
Belt - Fan; W/85 5/8" Belt O.C. ....	5H7371	②CX81
Belt - Gen.; Ser. No. 65A151 Thru 65A313 .	3S6272	♣9530HD
Belt - Gen.; Ser. No. 65A314 & After .....	2S5218	♣9580HD
<b>572F PS (96N)</b>		
<b>Caterpillar D333T Diesel</b>		
1974-1970		
Belt - Alt. ....	5M8135	②♣9520HD
Belt - Fan .....	3L6052	②TR30808
<b>572G</b>		
<b>Caterpillar 3306T Diesel</b>		
1995-1985		
Hose - Upper .....		24444
Hose - Lower - Eng. To Pipe .....		24440
Hose - Lower - Pipe To Rad. ....		24440
<b>583H (61A)</b>		
<b>Caterpillar D343T Diesel</b>		
1974-1960		
Belt - Alt.; W/1/2" Belt T.W.; W/64 1/4"		
Belt O.C. ....	8M8335	②♣9640HD
Belt - Alt.; W/3/4" Belt T.W.; W/64" Belt		
O.C. ....	1P2421	TR24638
Belt - Alt.; W/62 1/2" Belt O.C. ....	3P25	TR24619
Belt - Fan; W/75 7/8" Belt O.C. ....	2M8255	③TR30754
Belt - Fan; W/81 1/8" Belt O.C. ....	3L6052	③TR30808
Belt - Gen.; Ser. No. 61A1 Thru 61A96 .....	3S3961	♣9570HD
Belt - Gen.; Ser. No. 61A121 Thru 61A192 .	2S5218	♣9580HD
Belt - Gen.; Ser. No. 61A193 Thru 61A679 .	8M8335	♣9640HD
Belt - Gen.; Ser. No. 61A97 Thru 61A120 ...	2S2743	②♣9550HD
<b>594 (62H)</b>		
<b>Caterpillar D353TA Diesel</b>		
1975-1965		
Belt - Alt.; W/47" Belt O.C. ....	1S5138	TR24465
Belt - Alt.; W/48 1/8" Belt O.C. ....	5M5345	TR24476
Belt - Alt.; W/66 1/4" Belt O.C. ....	5S5249	♣9660HD
Belt - Fan; W/85 5/8" Belt O.C. ....	2P8624	②CX81

②Two Required ③Three Required ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CATERPILLAR - Continued</b>		
<b>Challenger 45</b>		
<b>Caterpillar 3116 Diesel</b>		
2001-1994		
Belt - A.C. ....	2P4191	▲9525HD
Belt - Fan & Alt. ....		②▲9700HD
Belt - W.P. ....		▲9345HD
<b>Challenger 65</b>		
<b>Caterpillar 3306 Diesel</b>		
1990-1986		
Belt - A.C. ....	9N1329	▲9425HD
Belt - Fan & Alt. ....	8M0959	②TR28786
Hose - Upper ....		②24440
Hose - Lower ....		②24440
Hose - By Pass ....		24244
<b>Challenger 65C</b>		
<b>Caterpillar 3306 Diesel</b>		
1996-1992		
Belt - Fan & Alt. ....		②TR30808
Hose - Upper ....		②24440
Hose - Lower ....		②24440
Hose - By Pass ....		24244
<b>Challenger 65E</b>		
<b>Caterpillar 3176 Diesel</b>		
2001-1997		
Belt - Fan & Alt. ....	8M0959	②TR28786
Belt - Fan To A.C. ....		▲9550HD
<b>Challenger 70C</b>		
<b>Caterpillar 3306 Diesel</b>		
1996-1994		
Belt - Fan & Alt. ....		②TR30808
Hose - Upper ....		②24440
Hose - Lower ....		②24440
Hose - By Pass ....		24244
<b>Challenger 75C</b>		
<b>Caterpillar 3176 Diesel</b>		
1996-1992		
Belt - Fan & Alt. ....	8M0959	②TR28786
Belt - Fan To A.C.; W/53 1/2" Belt O.C. ....		▲9530HD
Belt - Fan To A.C.; W/55 3/4" Belt O.C. ....		▲9555HD
Hose - Upper ....		●26512
Hose - Lower - Eng. To Pipe ....		②<21194
		or ●26519
Hose - Lower - Pipe To Rad. ....		24436
<b>Challenger 85C</b>		
<b>Caterpillar 3176 Diesel</b>		
1996-1993		
Belt - Fan & Alt. ....	8M0959	②TR28786
Belt - Fan To A.C.; W/53 1/2" Belt O.C. ....		▲9530HD
Belt - Fan To A.C.; W/55 3/4" Belt O.C. ....		▲9555HD
Hose - Upper ....		●26512
Hose - Lower - Eng. To Pipe ....		②<21194
		or ●26519
Hose - Lower - Pipe To Rad. ....		24436
<b>Challenger 85E</b>		
<b>Caterpillar 3196 Diesel</b>		
2001-1997		
Belt - Fan & Alt. ....	8M0959	②TR28786
Belt - Fan To A.C. ....		▲9550HD
<b>CBT</b>		
<b>8060</b>		
<b>Mercedes-Benz 6-Cyl. 346 Diesel</b>		
1993-1987		
Belt - Alt. ....		②▲9580HD
Belt - Hyd. Pump ....		▲9350HD

Application	OEM No.	Our No.
<b>CBT - Continued</b>		
<b>8240</b>		
<b>Perkins 4-Cyl. 248 Diesel</b>		
1991-1987		
Belt - Alt. ....		▲9560HD
Belt - Hyd. Pump ....		▲9350HD
<b>8260</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1991-1987		
Belt - Alt. ....		②▲9590HD
<b>CHALLENGER</b>		
<b>MT265</b>		
<b>Iseki 3-Cyl. 91 Diesel</b>		
2004-2002		
Belt - Fan ....	3607417M1	▲9385HD
<b>MT265B</b>		
<b>Iseki 3-Cyl. 91 Diesel</b>		
2009-2005		
Belt - Fan ....	3607417M1	▲9385HD
<b>MT285B</b>		
<b>Iseki 4-Cyl. 134 Diesel</b>		
2009-2005		
Belt - Fan ....	6243082M1	▲9412HD
<b>MT295B</b>		
<b>Iseki 4-Cyl. 180 Diesel</b>		
2009-2005		
Belt - Fan ....	4264647M1	▲9435HD
<b>MT297</b>		
<b>Iseki 4-Cyl. 173 Diesel</b>		
2004-2003		
Belt - Fan ....	4264647M1	▲9435HD
<b>MT297B</b>		
<b>Iseki 4-Cyl. 180 Diesel</b>		
2009-2007		
Belt - Fan ....	4264647M1	▲9435HD
<b>MT315B</b>		
<b>Challenger 3-Cyl. 201 Diesel</b>		
2009-2006		
Belt - Alt.; Ser. No. S13002 & Before ....	VA205892	▲9510HD
<b>MT325B; MT335B; MT345B</b>		
<b>Challenger 3-Cyl. 201 Diesel</b>		
2010-2006		
Belt - Alt.; Ser. No. S13002 & Before ....	VA205892	▲9510HD
<b>MT425</b>		
<b>Caterpillar 4-Cyl. 244 Diesel</b>		
2003-2002		
Belt - A.C. ....	1686883M1	▲9435HD
<b>MT425B</b>		
<b>Caterpillar 4-Cyl. 268 Diesel</b>		
2010-2004		
Belt - Fan ....	4274693M91	②▲9570HD

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>CHALLENGER - Continued</b>		
<b>MT445</b>		
<b>Caterpillar 4-Cyl. 256 Diesel</b>		
2003-2002		
Belt - A.C. ....	1686883M1	♣9435HD
<b>MT455; MT465</b>		
<b>Caterpillar 4-Cyl. 244 Diesel</b>		
2003-2002		
Belt - A.C. ....	1686883M1	♣9435HD
<b>MT525B</b>		
<b>Caterpillar 6-Cyl. 365 Diesel</b>		
2006-2004		
Belt - Compr. ....	4281725M1	K060642 or K060642RPM
<b>Caterpillar C6.6 Diesel</b>		
2011-2007		
Belt - Compr. ....	4281725M1	K060642 or K060642RPM
<b>MT535</b>		
<b>Caterpillar 6-Cyl. 365 Diesel</b>		
2003-2002		
Belt - A.C. ....	3386214M1	♣9465HD
Belt - Fan ....	3780606M91	♣9560HD
<b>MT535B</b>		
<b>Caterpillar 6-Cyl. 365 Diesel</b>		
2006-2004		
Belt - Compr. ....	4281725M1	K060642 or K060642RPM
<b>Caterpillar C6.6 Diesel</b>		
2011-2007		
Belt - Compr. ....	4281725M1	K060642 or K060642RPM
<b>MT545</b>		
<b>Caterpillar 6-Cyl. 365 Diesel</b>		
2003-2002		
Belt - A.C. ....	3386214M1	♣9465HD
<b>MT545B</b>		
<b>Caterpillar 6-Cyl. 365 Diesel</b>		
2006-2004		
Belt - Compr. ....	4281725M1	K060642 or K060642RPM
<b>Caterpillar C6.6 Diesel</b>		
2011-2007		
Belt - Compr. ....	4281725M1	K060642 or K060642RPM
<b>MT635B</b>		
<b>Sisu 6-Cyl. 451 Diesel</b>		
2009-2005		
Belt - Serpentine - Fan & Alt.; Ser. No. T128080 & Before .....	4284981M1	♣K080718HD
Belt - Serpentine - Fan & Alt.; Ser. No. T128081 & After .....	4296120M1	♣K080716HD
Belt - A.C.; Ser. No. T079034 & Before .....	4281345M1	♣K080433HD
<b>MT645</b>		
<b>Valmet 6-Cyl. 451 Diesel</b>		
2004-2002		
Belt - A.C. ....	3386214M1	♣9465HD
<b>MT645B</b>		
<b>Sisu 6-Cyl. 451 Diesel</b>		
2009-2005		
Belt - Serpentine - Fan & Alt.; Ser. No. T128080 & Before .....	4284981M1	♣K080718HD

♣Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>CHALLENGER - Continued</b>		
<b>MT645B - Continued</b>		
<b>Sisu 6-Cyl. 451 Diesel - Continued</b>		
2009-2005 - Continued		
Belt - Serpentine - Fan & Alt.; Ser. No. T128081 & After .....	4296120M1	♣K080716HD
Belt - A.C.; Ser. No. T079034 & Before .....	4281345M1	♣K080433HD
<b>MT655; MT665</b>		
<b>Valmet 6-Cyl. 513 Diesel</b>		
2004-2002		
Belt - A.C. ....	3386214M1	♣9465HD
<b>MT735</b>		
<b>Caterpillar C9 Diesel</b>		
2004-2002		
Belt - Fan & Alt. ....	202-0951	♣K080575HD
<b>MT745</b>		
<b>Caterpillar C9 Diesel</b>		
2005-2002		
Belt - Fan & Alt. ....	202-0951	♣K080575HD
<b>MT745C</b>		
<b>Caterpillar C9 Diesel</b>		
2011		
Belt - Fan & Alt. ....	202-0951	♣K080575HD
<b>MT755</b>		
<b>Caterpillar C9 Diesel</b>		
2005-2002		
Belt - Fan & Alt. ....	202-0951	♣K080575HD
<b>MT755B</b>		
<b>Caterpillar C9 Diesel</b>		
2008-2005		
Belt - Fan & Alt. ....	202-0951	♣K080575HD
<b>MT755C</b>		
<b>Caterpillar C9 Diesel</b>		
2011-2009		
Belt - Fan & Alt. ....	202-0951	♣K080575HD
<b>MT765</b>		
<b>Caterpillar C9 Diesel</b>		
2005-2002		
Belt - Fan & Alt. ....	202-0951	♣K080575HD
<b>MT765B</b>		
<b>Caterpillar C9 Diesel</b>		
2008-2005		
Belt - Fan & Alt. ....	202-0951	♣K080575HD
<b>MT765C</b>		
<b>Caterpillar C9 Diesel</b>		
2011-2009		
Belt - Fan & Alt. ....	202-0951	♣K080575HD
<b>MT835</b>		
<b>Caterpillar C12 Diesel</b>		
2005-2002		
Belt - Serpentine - Alt. ....	500685D1	♣K080956HD
<b>MT835B</b>		
<b>Caterpillar C12 Diesel</b>		
2005		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD

Agricultural Equipment



Application	OEM No.	Our No.
<b>CHALLENGER - Continued</b>		
<b>MT835B – Continued</b>		
<b>Caterpillar C15 Diesel</b>		
2008–2006		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT835C</b>		
<b>Caterpillar C15 Diesel</b>		
2013–2010		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT845</b>		
<b>Caterpillar C12 Diesel</b>		
2005–2002		
Belt - Serpentine - Alt. ....	500685D1	♣K080956HD
<b>MT845B</b>		
<b>Caterpillar C12 Diesel</b>		
2005		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>Caterpillar C15 Diesel</b>		
2008–2006		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT845C</b>		
<b>Caterpillar C15 Diesel</b>		
2013–2009		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT855</b>		
<b>Caterpillar C15 Diesel</b>		
2005–2002		
Belt - Serpentine - Alt. ....	500685D1	♣K080956HD
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT855B</b>		
<b>Caterpillar C15 Diesel</b>		
2008–2005		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT855C</b>		
<b>Caterpillar C15 Diesel</b>		
2013–2009		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT865</b>		
<b>Caterpillar C16 Diesel</b>		
2005–2002		
Belt - Serpentine - Alt. ....	500685D1	♣K080956HD
<b>MT865B</b>		
<b>Caterpillar C18 Diesel</b>		
2008–2005		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT865C</b>		
<b>Caterpillar C18 Diesel</b>		
2013–2009		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT875B</b>		
<b>Caterpillar C18 Diesel</b>		
2008–2005		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD

Application	OEM No.	Our No.
<b>CHALLENGER - Continued</b>		
<b>MT875C</b>		
<b>Caterpillar C18 Diesel</b>		
2013–2009		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT945B</b>		
<b>Caterpillar C15 Diesel</b>		
2008–2006		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT945C</b>		
<b>Caterpillar C15 Diesel</b>		
2013–2009		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT955B</b>		
<b>Caterpillar C15 Diesel</b>		
2008–2006		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT955C</b>		
<b>Caterpillar C15 Diesel</b>		
2013–2009		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT965B</b>		
<b>Caterpillar C18 Diesel</b>		
2008–2006		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT965C</b>		
<b>Caterpillar C18 Diesel</b>		
2013–2009		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT975B</b>		
<b>Caterpillar C18 Diesel</b>		
2008–2006		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>MT975C</b>		
<b>Caterpillar C18 Diesel</b>		
2013–2009		
Belt - Serpentine - Fan .....	197-6291	♣K140580HD
<b>COCKSHUTT</b>		
<b>20</b>		
<b>Continental 4–Cyl. 140</b>		
1958–1952		
Belt - Fan & Gen. ....	Z125	TR24414
<b>30</b>		
<b>Buda 4–Cyl. 153</b>		
1956–1946		
Belt - Fan & Gen. ....	T5031	TR28463
<b>Buda 4–Cyl. 153 Diesel</b>		
1956–1949		
Belt - Fan & Gen. ....	T5031	TR28463
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>Buda 4–Cyl. 153 LPG</b>		
1956–1946		
Belt - Fan & Gen. ....	T5031	TR28463
<b>35 Deluxe</b>		
<b>Hercules 4–Cyl. 198</b>		
1958–1956		
Belt - Fan & Gen. ....	Z555	♣9470HD
Belt - P.S. ....	Z577	7512

♣Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>COCKSHUTT - Continued</b>		
<b>40</b>		
<b>Buda 6-Cyl. 230</b>		
1958-1949		
Belt - Fan & Gen. ....	T5031	TR28463
Belt - P.S. ....	Z527	TR28483
Hose - Upper .....		24224
Hose - Lower .....		✕20065
<b>Buda 6-Cyl. 230 Diesel</b>		
1958-1950		
Belt - Fan & Gen. ....	T5031	TR28463
Belt - P.S. ....	Z527	TR28483
Hose - Upper .....		24224
Hose - Lower .....		✕20065
<b>50</b>		
<b>Buda 6-Cyl. 273</b>		
1958-1953		
Belt - Fan & Gen. ....	T5031	TR28463
Belt - P.S. ....	Z527	TR28483
Hose - Upper .....		24224
Hose - Lower .....		✕20065
<b>Buda 6-Cyl. 273 Diesel</b>		
1958-1953		
Belt - Fan & Gen. ....	T5031	TR28463
Belt - P.S. ....	Z527	TR28483
Hose - Upper .....		24224
Hose - Lower .....		✕20065
<b>540</b>		
<b>Continental 4-Cyl. 162</b>		
1962-1958		
Belt - Fan & Gen. ....	Z555	▲9470HD
Belt - P.S. ....	Z928	▲9540HD
<b>550</b>		
<b>Hercules 4-Cyl. 198</b>		
1962-1958		
Belt - Fan & Gen.; W/47 1/4" Belt O.C. ....	Z555	▲9470HD
Belt - Fan & Gen.; W/O P.S.; W/44 1/8" Belt O.C. ....		7440
Belt - Fan & Gen.; W/P.S.; W/45 5/8" Belt O.C. ....		7450
Belt - P.S. ....	Z880	▲9530HD
Hose - Upper .....		✕20065
	or	●25526
Hose - Lower; Ser. No. 127364 & Before .....		●25476
<b>Hercules 4-Cyl. 198 Diesel</b>		
1962-1958		
Belt - Fan & Gen. ....	Z555	▲9470HD
Belt - P.S. ....	Z880	▲9530HD
Hose - Upper .....		✕20065
	or	●25526
Hose - Lower; Ser. No. 127364 & Before .....		●25476
<b>560</b>		
<b>Perkins 4-Cyl. 269 Diesel</b>		
1962-1958		
Belt - Fan & Gen. ....	Z883	▲9500HD
Belt - P.S.; W/51 1/4" Belt O.C. ....	Z881	▲9510HD
Belt - P.S.; W/54 1/4" Belt O.C. ....	Z928	▲9540HD
<b>570</b>		
<b>Hercules 6-Cyl. 298</b>		
1960-1958		
Belt - Fan & Gen. ....	Z555	▲9470HD
Belt - P.S. ....	Z882	▲9550HD
<b>Hercules 6-Cyl. 298 Diesel</b>		
1960-1958		
Belt - Fan & Gen. ....	Z555	▲9470HD
Belt - P.S. ....	Z882	▲9550HD

Application	OEM No.	Our No.
<b>COCKSHUTT - Continued</b>		
<b>Golden Arrow</b>		
<b>Hercules 4-Cyl. 198</b>		
1957		
Belt - Fan & Gen. ....	Z555	▲9470HD
Belt - P.S. ....	Z671	7530
<b>CUB CADET</b>		
<b>5234D</b>		
<b>Daihatsu 3-Cyl. 51 Diesel</b>		
2008-2004		
Belt - Fan & Alt .....	BS-821075	7370
<b>7000; 7200; 7205</b>		
<b>Mitsubishi 3-Cyl. 69 Diesel</b>		
2003-1998		
Belt - Fan & Alt .....	MA-MD041704	7380
<b>7260</b>		
<b>Mitsubishi 3-Cyl. 80 Diesel</b>		
2003-1998		
Belt - Fan & Alt .....	MA-MD041704	7380
<b>7264</b>		
<b>Daihatsu 3-Cyl. 58 Diesel</b>		
2004-2003		
Belt - Fan & Alt .....	BS-821075	7370
<b>7265</b>		
<b>Mitsubishi 3-Cyl. 80 Diesel</b>		
2003-1998		
Belt - Fan & Alt .....	MA-MD041704	7380
<b>7272</b>		
<b>Mitsubishi 3-Cyl. 91 Diesel</b>		
1997-1995		
Belt - Fan & Alt .....	MA-MD027458	7375
<b>7273</b>		
<b>Mitsubishi 3-Cyl. 91 Diesel</b>		
1997-1996		
Belt - Fan & Alt .....	MA-MD027458	7375
<b>7274; 7275</b>		
<b>Mitsubishi 3-Cyl. 91 Diesel</b>		
1997-1995		
Belt - Fan & Alt .....	MA-MD027458	7375
<b>7300; 7305</b>		
<b>Mitsubishi 3-Cyl. 91 Diesel</b>		
2003-1998		
Belt - Fan & Alt.; Ser. No. 21495 & Before ...	MA-MD027458	7375
Belt - Fan & Alt.; Ser. No. 21496 & After .....	MA-MD041704	7380
<b>7360SS</b>		
<b>Mitsubishi 4-Cyl. 127 Diesel</b>		
2003-2000		
Belt - Fan & Alt .....	MA-MD088955	7385
<b>7530; 7532</b>		
<b>Mitsubishi 3-Cyl. 91 Diesel</b>		
2007-2004		
Belt - Fan & Alt .....	MA-MD041704	7380

✕Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>CUB CADET - Continued</b>		
<b>8354</b>		
<b>Dae Dong 3-Cyl. 101 Diesel</b>		
2007-2004		
Belt - Fan & Alt. ....	DDE580072531	▲9425HD
<b>8454</b>		
<b>Dae Dong 4-Cyl. 134 Diesel</b>		
2007-2004		
Belt - Fan & Alt. ....	DDE580072531	▲9425HD
<b>EX3200</b>		
<b>Yanmar 3-Cyl. 100 Diesel</b>		
2010-2008		
Belt - Fan .....	129211-42290	▲9395HD
<b>DAVID BROWN</b>		
<b>770</b>		
<b>David Brown 3-Cyl. 146 Diesel</b>		
1970-1965		
Belt - Fan & Gen. ....	912196	7430
Hose - Upper .....		●25472
<b>780</b>		
<b>David Brown 3-Cyl. 146 Diesel</b>		
1971-1967		
Belt - Fan & Gen. ....	912196	7430
Hose - Upper .....		●25472
<b>850</b>		
<b>David Brown 4-Cyl. 154 Diesel</b>		
1965-1960		
Belt - Fan & Gen. ....	A903050	7460
<b>880</b>		
<b>David Brown 3-Cyl. 154 Diesel</b>		
1971-1961		
Belt - Fan & Gen. ....	912196	7430
Belt - P.S. ....	913631	7360
Hose - Upper .....		●25472
<b>885</b>		
<b>David Brown 3-Cyl. 146</b>		
1980-1971		
Belt - Fan & Alt. ....	912196	7430
Belt - Fan & Gen. ....	901111	7450
<b>David Brown 3-Cyl. 164 Diesel</b>		
1980-1971		
Belt - Fan & Alt. ....	942053R	7417
Belt - Fan & Gen. ....	912196	7430
Belt - P.S. ....	913637R	7365
<b>900</b>		
<b>David Brown 4-Cyl. 164</b>		
1958-1956		
Belt - Fan & Gen. ....	A903050	7460
<b>David Brown 4-Cyl. 164 Diesel</b>		
1958-1956		
Belt - Fan & Gen. ....	A903050	7460
<b>990</b>		
<b>David Brown 4-Cyl. 185 Diesel</b>		
1980-1961		
Belt - Fan & Alt. ....	903050	7460
Belt - Fan & Gen.; Ser. No. 482001 Thru 800000 .....	901111	7450
Belt - Fan & Gen.; Ser. No. 800001 & After .	68073	7460
Hose - Upper; Early .....		24224
Hose - Upper - Left Side .....		≈<21660
		or ●25474

Application	OEM No.	Our No.
<b>DAVID BROWN - Continued</b>		
<b>990 - Continued</b>		
<b>David Brown 4-Cyl. 185 Diesel - Continued</b>		
1980-1961 - Continued		
Hose - Upper - Right Side .....		≈<20397
		or ●26519
<b>David Brown 4-Cyl. 195 Diesel</b>		
1980-1961		
Belt - Fan & Alt. ....	903050	7460
Belt - Fan & Gen.; Ser. No. 482001 Thru 800000 .....	901111	7450
Belt - Fan & Gen.; Ser. No. 800001 & After .	68073	7460
Hose - Upper; Early .....		24224
Hose - Upper - Left Side .....		≈<21660
		or ●25474
Hose - Upper - Right Side .....		≈<20397
		or ●26519
<b>995</b>		
<b>David Brown 4-Cyl. 219 Diesel</b>		
1980-1971		
Belt - Fan & Alt. ....	903050	7460
Belt - Fan & Gen.; Ser. No. 482001 Thru 800000 .....	901111	7450
Belt - Fan & Gen.; Ser. No. 800001 & After .	68073	7460
Hose - Upper - Left Side .....		≈<21660
		or ●25474
Hose - Upper - Right Side .....		≈<20397
		or ●26519
<b>996</b>		
<b>David Brown 4-Cyl. 219 Diesel</b>		
1976-1972		
Belt - Fan & Alt. ....	903050	7460
Belt - Fan & Gen.; Ser. No. 482001 Thru 800000 .....	901111	7450
Belt - Fan & Gen.; Ser. No. 800001 & After .	68073	7460
Hose - Upper - Left Side .....		≈<21660
		or ●25474
Hose - Upper - Right Side .....		≈<20397
		or ●26519
<b>1210</b>		
<b>David Brown 4-Cyl. 219 Diesel</b>		
1980-1971		
Belt - Fan & Alt. ....	68073	7460
Belt - Fan & Gen. ....	68073	7460
Hose - Upper - Left Side .....		≈<21660
		or ●25474
Hose - Upper - Right Side .....		≈<20397
		or ●26519
<b>1212</b>		
<b>David Brown 4-Cyl. 219 Diesel</b>		
1975-1971		
Belt - Fan & Alt. ....	68073	7460
Belt - Fan & Gen. ....	68073	7460
Hose - Upper - Left Side .....		≈<21660
		or ●25474
Hose - Upper - Right Side .....		≈<20397
		or ●26519
<b>1412</b>		
<b>David Brown 4-Cyl. 219 Diesel</b>		
1977-1975		
Hose - Upper .....		●25480
<b>3800</b>		
<b>David Brown 3-Cyl. 146</b>		
1972-1968		
Belt - Fan & Gen. ....	901111	7450
Hose - Upper .....		●25472

≈<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>DAVID BROWN - Continued</b>		
<b>4600</b>		
David Brown 3-Cyl. 164		
1972-1969		
Belt - Fan & Gen. ....	912196	7430
Hose - Upper .....		●25472
<b>DEUTZ-ALLIS</b>		
<b>5215</b>		
Hinomoto 3-Cyl. 61 Diesel		
1989-1986		
Belt - Fan & Alt. ....	A38	▲9390HD
<b>5220</b>		
Toyosha 3-Cyl. 87 Diesel		
1990-1986		
Belt - Fan & Alt. ....		▲9425HD
<b>5230</b>		
Toyosha 3-Cyl. 92 Diesel		
1991-1986		
Belt - Fan & Alt. ....		▲9425HD
Hose - Upper .....		●25251
Hose - Lower .....		●25252
<b>6070</b>		
Allis-Chalmers 4-Cyl. 200 Diesel		
1986-1985		
Belt - A.C. ....	562203	▲9440HD
Belt - Fan & Alt. ....	263408	▲9540HD
<b>6240</b>		
Deutz 3-Cyl. 173 Diesel		
1992-1985		
Belt - Blower & Alt. ....	01175765	7612
<b>6250</b>		
Deutz 3-Cyl. 173 Diesel		
1991-1985		
Belt - Blower & Alt. ....	01175765	7612
<b>6260</b>		
Deutz 3-Cyl. 187 Diesel		
1991-1985		
Belt - Blower & Alt. ....	01175765	7612
<b>6260F</b>		
Deutz 3-Cyl. 187 Diesel		
1991-1987		
Belt - Blower & Alt. ....	2235256	7580
<b>6265</b>		
Deutz 4-Cyl. 230 Diesel		
1991-1985		
Belt - Blower & Alt. ....	01175765	7612
<b>6275</b>		
Deutz 4-Cyl. 249 Diesel		
1991-1985		
Belt - Blower & Alt. ....	01175765	7612
<b>6275F; 6275L</b>		
Deutz 4-Cyl. 249 Diesel		
1991-1988		
Belt - Blower & Alt. ....	2235256	7580
<b>7085</b>		
Deutz 4-Cyl. 249 Diesel		
1991-1985		
Belt - A.C. ....	4342249	▲9570HD
Belt - Blower & Alt.; W/59 5/8" Belt O.C. ....	02235262	②7590

Application	OEM No.	Our No.
<b>DEUTZ-ALLIS - Continued</b>		
<b>7085 - Continued</b>		
Deutz 4-Cyl. 249 Diesel - Continued		
1991-1985 - Continued		
Belt - Blower & Alt.; W/63 5/8" Belt O.C. ....	02235265	②7630
<b>7110</b>		
Deutz 6-Cyl. 374 Diesel		
1991-1985		
Belt - A.C. ....	4325382	TR24664
<b>7120</b>		
Deutz 6-Cyl. 374 Diesel		
1991-1986		
Belt - Blower .....		7541
<b>7145</b>		
Deutz 6-Cyl. 374 Diesel		
1991-1986		
Belt - Alt. ....	2235180	7455
Belt - Blower .....	2234343	②7541
<b>8010</b>		
Allis-Chalmers 6-Cyl. 301 Diesel		
1989-1986		
Belt - A.C. ....	260149	9765
Belt - Fan & Alt. ....	254351	▲9560HD
Hose - Upper .....		②20731
		or ●26524
<b>8070</b>		
Allis-Chalmers 6-Cyl. 426 Diesel		
1989-1986		
Belt - Fan & Alt. ....	273193	②TR22664
<b>9130</b>		
Deutz 6-Cyl. 374 Diesel		
1992-1989		
Belt - A.C. ....		▲9390HD
Belt - Alt. ....		▲9480HD
<b>9150</b>		
Deutz 6-Cyl. 374 Diesel		
1992-1989		
Belt - A.C. ....	303535835	▲9380HD
Belt - Alt. ....	303526658	▲9480HD
Belt - Blower & Idler .....	02235177	②7550
<b>9170; 9190</b>		
Deutz 6-Cyl. 584 Diesel		
1992-1989		
Belt - A.C.; W/35 5/8" Belt O.C. ....	72160695	7350
Belt - A.C.; W/36 5/8" Belt O.C. ....	303527484	▲9360HD
Belt - A.C.; W/36 7/8" Belt O.C. ....		▲9365HD
Belt - Alt.; W/33 5/8" Belt O.C. ....	303526682	②7330
Belt - Alt.; W/34 1/8" Belt O.C. ....		②7335
<b>DEUTZ-FAHR</b>		
<b>D30-06</b>		
Deutz 2-Cyl. 115 Diesel		
1979-1969		
Belt - Blower & Gen. ....		7455
<b>D40-06</b>		
Deutz 3-Cyl. 173 Diesel		
1978-1969		
Belt - Blower & Alt. ....		7590

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>DEUTZ-FAHR - Continued</b>		
<b>D45-06</b>		
Deutz 3-Cyl. 173 Diesel		
1980-1972		
Belt - Blower & Alt. ....		7590
<b>D62-06</b>		
Deutz 4-Cyl. 230 Diesel		
1981-1974		
Belt - Blower & Alt. ....		7590
<b>D68-06</b>		
Deutz 4-Cyl. 230 Diesel		
1980-1974		
Belt - Blower & Alt. ....		7590
<b>D80-06</b>		
Deutz 6-Cyl. 345 Diesel		
1979-1972		
Belt - Blower & Alt. ....		7612
<b>DX90</b>		
Deutz 5-Cyl. 287 Diesel		
1984-1979		
Belt - A.C. ....	▲9350HD	
Belt - Alt. ....	0033566	7480
Belt - Blower ....	2232958	7530
Belt - Blower & Alt. ....	②7612	
Belt - Hyd. Pump ....	0033567	▲9540HD
<b>DX110</b>		
Deutz 6-Cyl. 345 Diesel		
1980-1979		
Belt - A.C. ....	▲9350HD	
Belt - Blower & Alt. ....	②7612	
<b>DX120; DX130</b>		
Deutz 6-Cyl. 374 Diesel		
1984-1980		
Belt - A.C. ....	▲9350HD	
Belt - Blower & Alt. ....	▲9610HD	
<b>DX140</b>		
Deutz 6-Cyl. 374 Diesel		
1980-1979		
Belt - Alt. ....		7455
<b>DX160</b>		
Deutz 6-Cyl. 374 Diesel		
1984-1979		
Belt - A.C. ....	▲9350HD	
Belt - Blower & Alt. ....	▲9610HD	
<b>DRESSER-DRESSTA</b>		
<b>TD7E</b>		
IH D239 Diesel		
1988-1974		
Belt - Fan ....	621770C1	▲9555HD
<b>TD7G</b>		
Dresser D240N Diesel		
1994-1987		
Belt - Fan & Alt. ....	1240873H1	▲K080560HD
<b>TD8E</b>		
IH DT239 Diesel		
1987-1974		
Belt - Fan ....	621770C1	▲9555HD

Application	OEM No.	Our No.
<b>DRESSER-DRESSTA - Continued</b>		
<b>TD8G</b>		
Dresser D240T Diesel		
1994-1987		
Belt - Fan & Alt.; W/56 5/8" Belt O.C. ....	1240873H1	▲K080560HD
Belt - Fan & Alt.; W/62 5/8" Belt O.C. ....	1257759H1	▲K080620HD
<b>TD12</b>		
IH D466B Diesel		
1994-1981		
Belt - Fan & Alt. ....	1213134H91	②TR22664
<b>TD15C</b>		
Dresser D505T Diesel		
1995-1972		
Belt - Fan & Alt. ....	1257770H1	▲K080610HD
<b>IH DT466 Diesel</b>		
1995-1972		
Belt - Alt.; Ser. No. 17399 & Before ....	673481C1	TR22648
Belt - Alt.; Ser. No. 17400 & After ....	1213134H91	②TR22664
<b>TD15C Articulated</b>		
Dresser D505T Diesel		
2001-1972		
Belt - Fan & Alt. ....	1257762H1	▲K080605HD
<b>TD15E</b>		
Dresser D505T Diesel		
1995-1986		
Belt - A.C. ....	1251357H1	▲9425HD
Belt - Fan & Alt. ....	1253462H1	▲K080670HD
Hose - Upper - Eng. To Pipe ....		24436
Hose - Upper - Pipe To Rad. ....		24436
Hose - Lower - Eng. To Pipe ....		≈21473
<b>IH DT466C Diesel</b>		
1995-1986		
Belt - Fan & Alt. ....	1213134H91	②TR22664
<b>TD20E</b>		
IH DVT800 Diesel		
1986-1974		
Belt - A.C. ....		▲9680HD
Belt - Alt.; Ser. No. 30277 & Before ....	683723C1	▲9476HD
Belt - Alt.; Ser. No. 30278 & After ....	673029C1	▲9470HD
Belt - Fan ....	673946C91	④TR22752
<b>TD20G</b>		
Cummins LTA10C Diesel		
1996-1986		
Belt - A.C. ....		TR24562
Belt - Alt. ....	1246253H1	K050317
Belt - Fan ....	1246274H1	▲K080605HD
<b>TD25E</b>		
IH DT817C Diesel		
1985-1979		
Belt - Fan & Alt.; Ser. No. 12007 & Before ....		TR22517
Belt - Fan & Alt.; Ser. No. 12008 & After ....	326998R1	②TR22570
<b>TD25G</b>		
Cummins KT19C Diesel		
2001-1987		
Belt - A.C. ....		TR22664
Belt - Alt. ....	1238776H1	K050370
Hose - Upper - Eng. To Pipe ....		②24440
Hose - Upper - Pipe To Rad. ....		②24440
<b>TD40</b>		
Cummins KTA1150C Diesel		
1991-1933		
Belt - A.C. ....		TR22664
Belt - Alt. ....	1238776H1	K050370

②Two Required ④Four Required ≈Cut to Fit ▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>DRESSER-DRESSTA - Continued</b>		
<b>TD40B</b>		
Cummins KTA19C Diesel		
1995-1988		
Belt - A.C. ....		TR22664
Belt - Alt. ....	1238776H1	K050370
<b>EUCLID</b>		
<b>82-40</b>		
Detroit Diesel 8V-71N Diesel		
1968-1966		
Belt - Fan & Gen. ....	9177465	②BX77
<b>C6-1; C6-2; C6-3; C6-4; C6-5</b>		
Detroit Diesel 6-71 Diesel		
1963-1959		
Belt - Gen.; W/34 1/8" Belt O.C. ....	2068846	TR22336
Belt - Gen.; W/44 3/4" Belt O.C. ....	9174657	TR22443
<b>FERGUSON</b>		
<b>40</b>		
Continental 4-Cyl. 134		
1956		
Belt - Fan & Gen. ....	181523M1	♣9430HD
Hose - Upper ....		24224
<b>F40</b>		
Continental 4-Cyl. 134		
1957-1956		
Belt - Fan & Gen. ....	509572M1	♣9425HD
Hose - Upper ....		●25476
<b>TE20</b>		
Continental 4-Cyl. 120		
1951-1948		
Belt - Fan & Gen. ....	TO8620	TR28406
Hose - Upper ....		24224
Hose - Lower ....		⊗20386
		or ●25476
<b>TEA20</b>		
Standard Motors 23C		
1956-1948		
Belt - Fan & Gen.; Ser. No. 132206 & Before ....	825660M1	TR24407
Standard Motors 23C Diesel		
1956-1948		
Belt - Fan & Gen.; Ser. No. 132206 & Before ....	825660M1	TR24407
<b>TO20</b>		
Continental 4-Cyl. 120		
1951-1947		
Belt - Fan & Gen. ....	TO8620	TR28406
Hose - Upper ....		24224
Hose - Lower ....		⊗20386
		or ●25476
<b>TO30</b>		
Continental 4-Cyl. 129		
1954-1951		
Belt - Fan & Gen. ....	181636M1	TR28406
Hose - Upper ....		24224
Hose - Lower ....		⊗20386
		or ●25476
<b>TO35</b>		
Continental 4-Cyl. 134		
1957-1954		
Belt - Fan & Gen. ....	509572M1	♣9425HD
Hose - Upper ....		24224
Hose - Lower ....		●25473

Application	OEM No.	Our No.
<b>FERGUSON - Continued</b>		
<b>TO35 - Continued</b>		
Standard Motors 4-Cyl. 137 Diesel		
1957-1954		
Belt - Fan & Gen. ....	184930M1	TR28423
Hose - Upper ....		24224
Hose - Lower ....		⊗20226
		or ●25477
Hose - By Pass ....		24218
<b>FERRARI</b>		
<b>86</b>		
Lamborghini 3-Cyl. 151 Diesel		
1989-1978		
Belt - Blower ....		②7395
<b>94L</b>		
Lamborghini 2-Cyl. 81 Diesel		
1982-1981		
Belt - Blower ....		3V315
<b>95</b>		
Lamborghini 2-Cyl. 81 Diesel		
1989-1981		
Belt - Blower ....		3V315
<b>1300</b>		
Lamborghini 2-Cyl. 81 Diesel		
1989-1987		
Belt - Blower ....		3V315
<b>FIAT</b>		
<b>F110; F130</b>		
Fiat 6-Cyl. 358 Diesel		
1995-1990		
Belt - Fan & Idler ....		7435
Belt - Fan To Alt. & Idler ....		7475
<b>FORD</b>		
<b>2N</b>		
Ford 4-Cyl. 120		
1947-1942		
Belt - Fan & Gen.; Ser. No. 263842 & Before ....	9N 8620 B	TR20451
Belt - Fan & Gen.; Ser. No. 263843 & After .	8N 8620	TR20412
<b>8N</b>		
Ford 4-Cyl. 120		
1952-1947		
Belt - Fan & Gen.; Ser. No. 8N263843 & Before ....	9N 8620 B	TR20451
Belt - Fan & Gen.; Ser. No. 8N263844 & After ....	8N 8620	TR20412
Hose - Upper ....		24224
Hose - Lower; Ser. No. 8N263843 & Before ....		20065
Hose - Lower; Ser. No. 8N263844 & After ....		20166
		or ●25476
<b>9N</b>		
Ford 4-Cyl. 120		
1942-1939		
Belt - Fan & Gen.; Ser. No. 263842 & Before ....	9N 8620 B	TR20451
Belt - Fan & Gen.; Ser. No. 263843 & After .	8N 8620	TR20412
<b>335 Industrial</b>		
Ford 3-Cyl. 175		
1980-1975		
Belt - Fan & Alt. ....	C9NN 10C318 A	♣9555HD
Hose - Upper ....		●25804

②Two Required ⊗Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>420 Industrial</b>		
<b>Ford 4-Cyl. 183 Diesel</b>		
1988-1975		
Belt - Fan & Alt. ....	C9NN 10C318 A	▲9555HD
Hose - Upper .....		☞<21794
		or ●25474
<b>445 Industrial</b>		
<b>Ford 4-Cyl. 183 Diesel</b>		
1985-1980		
Belt - Fan & Alt. ....		▲9560HD
Hose - Upper .....		☞<20065
<b>501</b>		
<b>Ford 4-Cyl. 134</b>		
1962-1958		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>Ford 4-Cyl. 144 Diesel</b>		
1962-1958		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>540 Industrial</b>		
<b>Ford 3-Cyl. 201 Diesel</b>		
1985-1980		
Belt - Fan & Alt.; W/O 72A. Alt. ....	D6NN 8620 A	▲9463HD
Belt - W.P. & Alt.; W/72A. Alt. ....	D7NN 10C318 A	▲9313HD
Hose - Upper .....		☞<20065
<b>555 Industrial</b>		
<b>Ford 3-Cyl. 201</b>		
1985-1980		
Belt - Fan & Alt.; W/O 72A. Alt. ....	D6NN 8620 A	▲9463HD
Belt - W.P. & Alt.; W/72A. Alt. ....	D7NN 10C318 A	▲9313HD
Hose - Upper .....		☞<20065
<b>Ford 3-Cyl. 201 Diesel</b>		
1985-1980		
Belt - Fan & Alt.; W/O 72A. Alt. ....	D6NN 8620 A	▲9463HD
Belt - W.P. & Alt.; W/72A. Alt. ....	D7NN 10C318 A	▲9313HD
Hose - Upper .....		☞<20065
<b>611</b>		
<b>Ford 4-Cyl. 134</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>Ford 4-Cyl. 134 LPG</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>Ford 4-Cyl. 144 Diesel</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660

Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>620</b>		
<b>Ford 4-Cyl. 134</b>		
1957-1954		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>Ford 4-Cyl. 134 LPG</b>		
1957-1954		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>621</b>		
<b>Ford 4-Cyl. 134</b>		
1962-1959		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>Ford 4-Cyl. 134 LPG</b>		
1962-1959		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>Ford 4-Cyl. 144 Diesel</b>		
1962-1959		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>630</b>		
<b>Ford 4-Cyl. 134</b>		
1957-1954		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>Ford 4-Cyl. 134 LPG</b>		
1957-1954		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>631</b>		
<b>Ford 4-Cyl. 134</b>		
1962-1959		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>Ford 4-Cyl. 134 LPG</b>		
1962-1959		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞<21660

☞<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>740 - Continued</b>		
<b>Ford 4-Cyl. 134 LPG - Continued</b>		
1957-1954 - Continued		
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>741; 771</b>		
<b>Ford 4-Cyl. 134</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>Ford 4-Cyl. 134 LPG</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>Ford 4-Cyl. 144 Diesel</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>811</b>		
<b>Ford 4-Cyl. 172</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>Ford 4-Cyl. 172 Diesel</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>Ford 4-Cyl. 172 LPG</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>820</b>		
<b>Ford 4-Cyl. 172</b>		
1957-1954		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>Ford 4-Cyl. 172 LPG</b>		
1957-1954		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660

Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>821</b>		
<b>Ford 4-Cyl. 172</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>Ford 4-Cyl. 172 Diesel</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>Ford 4-Cyl. 172 LPG</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>840</b>		
<b>Ford 4-Cyl. 172</b>		
1957-1954		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>Ford 4-Cyl. 172 LPG</b>		
1957-1954		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>841</b>		
<b>Ford 4-Cyl. 172</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>Ford 4-Cyl. 172 Diesel</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>Ford 4-Cyl. 172 LPG</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	♣9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	♣9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	♣9415HD
Hose - Upper .....		24220
Hose - Lower .....		♣<21660
<b>846</b>		
<b>Cummins 6-Cyl. 611 Diesel</b>		
1993-1988		
Belt - A.C.; W/38 7/8" Belt O.C. ....	00092756	②♣9385HD
Belt - A.C.; W/40" Belt O.C. ....	13C1025	②A38
Belt - Alt. ....	3037425	♣K050340HD
Belt - Fan .....	3034944	♣K080545HD

②Two Required ♣Cut to Fit ♣Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>850</b>		
<b>Ford 4-Cyl. 172</b>		
1957-1954		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>Ford 4-Cyl. 172 LPG</b>		
1957-1954		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>851</b>		
<b>Ford 4-Cyl. 172</b>		
1962-1957		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>Ford 4-Cyl. 172 Diesel</b>		
1962-1957		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>Ford 4-Cyl. 172 LPG</b>		
1962-1957		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>856</b>		
<b>Cummins 6-Cyl. 611 Diesel</b>		
1991-1988		
Belt - A.C.; W/38 7/8" Belt O.C. ....	00092756	②▲9385HD
Belt - A.C.; W/40" Belt O.C. ....	13C1025	②A38
Belt - Alt. ....	3037425	▲K050340HD
Belt - Fan ....	3034944	▲K080545HD
<b>860</b>		
<b>Ford 4-Cyl. 172</b>		
1957-1954		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>Ford 4-Cyl. 172 LPG</b>		
1957-1954		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>861; 871</b>		
<b>Ford 4-Cyl. 172</b>		
1962-1957		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	

Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>861; 871 - Continued</b>		
<b>Ford 4-Cyl. 172 Diesel</b>		
1962-1957		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>Ford 4-Cyl. 172 LPG</b>		
1962-1957		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>876</b>		
<b>Cummins 6-Cyl. 611 Diesel</b>		
1991-1988		
Belt - A.C.; W/38 7/8" Belt O.C. ....	00092756	②▲9385HD
Belt - A.C.; W/40" Belt O.C. ....	13C1025	②A38
Belt - Alt. ....	3037425	▲K050340HD
Belt - Fan ....	3034944	▲K080545HD
Hose - Upper - Eng. To Pipe .....		24436
Hose - Upper - Pipe To Rad. ....		24436
Hose - Lower - Eng. To Pipe .....		24440
Hose - Lower - Pipe To Rad. ....		24440
Hose - By Pass .....		24226
<b>881; 941</b>		
<b>Ford 4-Cyl. 172</b>		
1962-1957		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>Ford 4-Cyl. 172 Diesel</b>		
1962-1957		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>Ford 4-Cyl. 172 LPG</b>		
1962-1957		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	
<b>946</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1993-1987		
Belt - A.C. ....		②▲9430HD
Belt - Alt. ....		▲9463HD
Belt - Fan ....	178707	②TR28437
Belt - W.P. ....	217638	▲K060435HD
Hose - Upper .....		●26524
Hose - Lower - Eng. To Pipe .....		24440
Hose - Lower - Pipe To Rad. ....		24440
<b>950</b>		
<b>Ford 4-Cyl. 172</b>		
1957-1954		
Belt - Fan & Gen. ....	EAF 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAF 8577 A	▲9415HD
Hose - Upper .....	24220	
Hose - Lower .....	≧21660	

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>950 - Continued</b>		
<b>Ford 4-Cyl. 172 LPG</b>		
1957-1954		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞21660
<b>951</b>		
<b>Ford 4-Cyl. 172</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞21660
<b>Ford 4-Cyl. 172 Diesel</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞21660
<b>Ford 4-Cyl. 172 LPG</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞21660
<b>960</b>		
<b>Ford 4-Cyl. 172</b>		
1957-1954		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞21660
<b>Ford 4-Cyl. 172 LPG</b>		
1957-1954		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞21660
<b>961; 971; 981</b>		
<b>Ford 4-Cyl. 172</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞21660
<b>Ford 4-Cyl. 172 Diesel</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞21660
<b>Ford 4-Cyl. 172 LPG</b>		
1962-1957		
Belt - Fan & Gen. ....	EAJ 8577 A	▲9415HD
Belt - P.S.; Ser. No. 89929 & Before .....	310050	▲9470HD
Belt - P.S.; Ser. No. 89930 & After .....	EAJ 8577 A	▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		☞21660

Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>1000</b>		
<b>Shibaura 2-Cyl. 78 Diesel</b>		
1978-1973		
Belt - Fan & Alt. ....		▲9440HD
Hose - Upper .....		●25252
<b>1100</b>		
<b>Shibaura 2-Cyl. 43 Diesel</b>		
1983		
Belt - Fan & Alt. ....	9845513	7320
Hose - Lower .....		☞20065
1982-1979		
Belt - Fan & Alt. ....		7325
Hose - Lower .....		☞20065
<b>1110</b>		
<b>Shibaura 2-Cyl. 43 Diesel</b>		
1989-1984		
Belt - Fan & Alt. ....	9845513	7320
<b>1200</b>		
<b>Shibaura 2-Cyl. 49 Diesel</b>		
1983-1980		
Belt - Fan & Alt. ....		7325
<b>1210</b>		
<b>Shibaura 3-Cyl. 54 Diesel</b>		
1989-1983		
Belt - Fan & Alt. ....		7315
<b>1300</b>		
<b>Shibaura 2-Cyl. 49 Diesel</b>		
1982-1979		
Belt - Fan & Alt. ....		7325
Hose - Lower .....		☞20065
<b>1500</b>		
<b>Shibaura 2-Cyl. 61 Diesel</b>		
1983-1979		
Belt - Fan & Alt.; W/35 1/8" Belt O.C. ....		7350
Belt - Fan & Alt.; W/44 1/4" Belt O.C. ....		▲9440HD
Hose - Upper .....		☞21794
	or	●25474
<b>Shibaura 2-Cyl. 69 Diesel</b>		
1983-1979		
Belt - Fan & Alt.; W/35 1/8" Belt O.C. ....		7350
Belt - Fan & Alt.; W/44 1/4" Belt O.C. ....		▲9440HD
Hose - Upper .....		☞21794
	or	●25474
<b>1600</b>		
<b>Shibaura 2-Cyl. 78 Diesel</b>		
1979-1976		
Belt - Fan & Alt.; W/35 1/8" Belt O.C. ....		7350
Belt - Fan & Alt.; W/44 1/4" Belt O.C. ....		▲9440HD
<b>1700</b>		
<b>Shibaura 2-Cyl. 78 Diesel</b>		
1983-1979		
Belt - Fan & Alt.; W/35 1/8" Belt O.C. ....		7350
Belt - Fan & Alt.; W/44 1/4" Belt O.C. ....		▲9440HD
Hose - Upper .....		☞21794
	or	●25476
Hose - Lower .....		☞20168
	or	●25476
<b>1710</b>		
<b>Shibaura 3-Cyl. 85 Diesel</b>		
1986-1983		
Belt - Fan & Alt. ....		7350
Hose - Upper .....		20661
	or	●25251

☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>1710 – Continued</b>		
<b>Shibaura 3–Cyl. 85 Diesel – Continued</b>		
1986–1983 – Continued		
Hose - Lower .....		●25252
<b>1900</b>		
<b>Shibaura 3–Cyl. 87 Diesel</b>		
1983–1979		
Belt - Fan & Alt. ....	SBA080220043	A43
<b>2000</b>		
<b>Ford 3–Cyl. 158</b>		
1975–1962		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		●25480
Hose - Lower .....		●26502
<b>Ford 3–Cyl. 158 Diesel</b>		
1975–1962		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		≧<21794
	or	●25480
Hose - Lower .....		●26502
<b>2100</b>		
<b>Ford 3–Cyl. 158</b>		
1975–1967		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		●25480
Hose - Lower .....		●26502
<b>Ford 3–Cyl. 158 Diesel</b>		
1975–1967		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		≧<21794
	or	●25480
Hose - Lower .....		●26502
<b>2310</b>		
<b>Ford 3–Cyl. 158 Diesel</b>		
1985–1982		
Belt - Fan .....	D3NN 10C318 D	▲9550HD
<b>2600</b>		
<b>Ford 3–Cyl. 158</b>		
1981–1977		
Belt - A.C. ....	86514609	▲9350HD
Belt - Alt. ....	9604339	▲9550HD
Belt - Fan; W/A.C. ....	86518903	9270
<b>Ford 3–Cyl. 158 Diesel</b>		
1981–1977		
Belt - A.C. ....	86514609	▲9350HD
Belt - Alt. ....	9604339	▲9550HD
Belt - Fan; W/A.C. ....	86518903	9270
1976		
Belt - Alt. ....	9604339	▲9550HD
<b>2610</b>		
<b>Ford 3–Cyl. 158</b>		
1983–1982		
Belt - Fan .....	D3NN 10C318 D	▲9550HD
<b>Ford 3–Cyl. 175 Diesel</b>		
1983–1982		
Belt - Fan .....	D3NN 10C318 D	▲9550HD

Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>3000</b>		
<b>Ford 3–Cyl. 158</b>		
1976–1965		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		●25480
Hose - Lower .....		●26502
<b>Ford 3–Cyl. 175 Diesel</b>		
1976–1965		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		≧<21794
	or	●25480
Hose - Lower .....		●26502
<b>3100</b>		
<b>Ford 3–Cyl. 158</b>		
1975–1966		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		●25480
Hose - Lower .....		●26502
<b>Ford 3–Cyl. 175 Diesel</b>		
1975–1966		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		≧<21794
	or	●25480
Hose - Lower .....		●26502
<b>3300; 3310</b>		
<b>Ford 3–Cyl. 175 Diesel</b>		
1975–1968		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
<b>3330</b>		
<b>Ford 3–Cyl. 158</b>		
1975–1968		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		●25480
Hose - Lower .....		●26502
<b>Ford 3–Cyl. 175 Diesel</b>		
1975–1968		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		≧<21794
	or	●25480
Hose - Lower .....		●26502
<b>3400</b>		
<b>Ford 3–Cyl. 175</b>		
1975–1965		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
Hose - Upper .....		≧<21794
	or	●25480
Hose - Lower .....		●26502
<b>3550 Industrial</b>		
<b>Ford 3–Cyl. 183 Diesel</b>		
1978–1973		
Hose - Upper .....		≧<20065
	or	●25526
<b>3600</b>		
<b>Ford 3–Cyl. 175</b>		
1981–1975		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD

≧<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>3600 - Continued</b>		
<b>Ford 3-Cyl. 175 - Continued</b>		
1981-1975 - Continued		
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
<b>Ford 3-Cyl. 175 Diesel</b>		
1981-1975		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
<b>3610</b>		
<b>Ford 3-Cyl. 175</b>		
1983-1982		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
<b>Ford 3-Cyl. 192 Diesel</b>		
1983-1982		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
Hose - Upper .....		⊖<21794
		or ●25476
<b>4000</b>		
<b>Ford 3-Cyl. 201</b>		
1975-1965		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		●25478
Hose - Lower .....		20229
		or ●26502
<b>Ford 3-Cyl. 201 Diesel</b>		
1975-1965		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		⊖<20065
		or ●25473
<b>4100</b>		
<b>Ford 3-Cyl. 183</b>		
1981-1976		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
Hose - Upper .....		⊖<21794
		or ●25474
<b>Ford 3-Cyl. 183 Diesel</b>		
1981-1976		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
Hose - Upper .....		⊖<21794
		or ●25474
<b>4330; 4340</b>		
<b>Ford 3-Cyl. 201 Diesel</b>		
1975-1968		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		⊖<20065
		or ●25473
<b>4400</b>		
<b>Ford 3-Cyl. 192</b>		
1974-1968		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD

Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>4400 Industrial</b>		
<b>Ford 3-Cyl. 192</b>		
1974-1968		
Hose - Upper .....		●25804
<b>Ford 3-Cyl. 201 Diesel</b>		
1974-1968		
Hose - Upper .....		⊖<20065
		or ●25526
<b>4500 Industrial</b>		
<b>Ford 3-Cyl. 201 Diesel</b>		
1973-1967		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
Hose - Upper .....		⊖<20065
		or ●25473
Hose - Lower .....		●26502
<b>4600</b>		
<b>Ford 3-Cyl. 201</b>		
1981-1975		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
<b>Ford 3-Cyl. 201 Diesel</b>		
1981-1975		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
<b>4600SU</b>		
<b>Ford 3-Cyl. 201</b>		
1981-1976		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
<b>Ford 3-Cyl. 201 Diesel</b>		
1981-1976		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
<b>4830</b>		
<b>Ford 3-Cyl. 256 Diesel</b>		
1993-1989		
Belt - Fan & Alt. ....	F7NN 20C318 BA	▲9560HD
Hose - Upper .....		⊖<21794
<b>5000</b>		
<b>Ford 4-Cyl. 233</b>		
1967-1962		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		●25480
<b>Ford 4-Cyl. 233 Diesel</b>		
1967-1962		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		⊖<21794
		or ●25480
<b>Ford 4-Cyl. 256</b>		
1975-1968		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		●25480
<b>Ford 4-Cyl. 256 Diesel</b>		
1975-1968		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD

⊖<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>5000 - Continued</b>		
<b>Ford 4-Cyl. 256 Diesel - Continued</b>		
1975-1968 - Continued		
Hose - Upper .....		≧<21794 or ●25480
<b>5100</b>		
<b>Ford 4-Cyl. 256</b>		
1976-1965		
Belt - Fan & Alt./Gen. ....		▲9550HD
Belt - P.S. ....	EAF 8577 A	▲9415HD
Hose - Upper .....		≧<20065 or ●25526
Hose - Lower .....		●26502
<b>5600</b>		
<b>Ford 4-Cyl. 233 Diesel</b>		
1981-1975		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
Hose - Upper .....		≧<21794 or ●25474
<b>6000</b>		
<b>Ford 6-Cyl. 223</b>		
1967-1961		
Belt - Fan .....	CONN 8A602 B	7340
Belt - W.P. & Gen. ....	CONN 8620 B	②7380
Hose - Upper .....		●25480
Hose - Lower .....		24228
<b>Ford 6-Cyl. 242 Diesel</b>		
1967-1961		
Belt - Fan .....	CONN 8A602 B	7340
Belt - W.P. & Gen. ....	CONN 8620 B	②7380
Hose - Upper .....		●25480
Hose - Lower .....		24228
<b>6100</b>		
<b>Ford 6-Cyl. 223</b>		
1967-1963		
Belt - Fan .....	CONN 8A602 B	7340
Belt - W.P. & Gen. ....	CONN 8620 B	②7380
Hose - Upper .....		●25480
Hose - Lower .....		24228
<b>Ford 6-Cyl. 242 Diesel</b>		
1967-1963		
Belt - Fan .....	CONN 8A602 B	7340
Belt - W.P. & Gen. ....	CONN 8620 B	②7380
Hose - Upper .....		●25480
Hose - Lower .....		24228
<b>6600</b>		
<b>Ford 4-Cyl. 256</b>		
1981-1975		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
Hose - Upper .....		≧<21794 or ●25474
<b>Ford 4-Cyl. 256 Diesel</b>		
1981-1975		
Belt - Fan & Alt. ....		▲9550HD
Hose - Upper .....		●25480
<b>6700</b>		
<b>Ford 4-Cyl. 255 Diesel</b>		
1981-1977		
Belt - A.C. ....	C9NN 10C318 B	▲9545HD
Belt - Alt. ....	9604339	▲9550HD
Belt - Fan; W/A.C. ....	86518903	9270

Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>6700 EC2</b>		
<b>Ford 4-Cyl. 255 Diesel</b>		
1982-1977		
Belt - Fan .....	D5NN 8620 A	▲9463HD
Belt - Fan & Alt. ....	C9NN 8620 A	▲9555HD
<b>6710 EC3</b>		
<b>Ford 4-Cyl. 268 Diesel</b>		
1981-1977		
Belt - A.C. ....	C9NN 10C318 B	▲9555HD
Belt - Alt. ....	D5NN 10C318 A	▲9325HD
Belt - Fan .....	D6NN 8620 A	▲9463HD
Belt - Fan To Alt. ....	D5NN 10C318 C	▲9305HD
Hose - Upper .....		≧<21794 or ●25480
<b>7000</b>		
<b>Ford 4-Cyl. 256 Diesel</b>		
1975-1971		
Belt - Fan & Alt./Gen. ....	C9NN 10C318 A	▲9555HD
Hose - Upper .....		≧<21794 or ●25480
<b>7100</b>		
<b>Ford 4-Cyl. 256 Diesel</b>		
1975-1973		
Belt - Fan & Alt./Gen. ....	C9NN 10C318 A	▲9555HD
Hose - Upper .....		≧<20065 or ●25526
<b>7200</b>		
<b>Ford 4-Cyl. 256 Diesel</b>		
1975-1973		
Belt - Fan & Alt./Gen. ....	C9NN 10C318 A	▲9555HD
Hose - Upper .....		≧<21794 or ●25480
<b>7400 FC1</b>		
<b>Ford 4-Cyl. 256 Diesel</b>		
1976-1975		
Belt - Fan & Alt./Gen. ....	C9NN 10C318 A	▲9555HD
Hose - Upper .....		≧<21794 or ●25480
<b>7600</b>		
<b>Ford 4-Cyl. 255 Diesel</b>		
1981-1975		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
Hose - Upper .....		●25480
<b>Ford 4-Cyl. 268 Diesel</b>		
1981-1975		
Belt - Fan & Alt.; W/55 1/4" Belt O.C. ....		▲9550HD
Belt - Fan & Alt.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - W.P. & Alt. ....	D5NN 10C318 A	▲9325HD
Hose - Upper .....		●25480
<b>7700</b>		
<b>Ford 4-Cyl. 255 Diesel</b>		
1983-1976		
Belt - A.C.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9465HD
Belt - A.C.; W/55 3/4" Belt O.C. ....	C9NN 8620 A	▲9555HD
Belt - Alt. ....	D5NN 10C318 A	▲9325HD
Belt - Fan .....	D6NN 8620 A	▲9463HD
Belt - Fan & P.S. ....	D6NN 8620 A	▲9463HD
<b>Ford 4-Cyl. 268 Diesel</b>		
1983-1976		
Belt - A.C.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9465HD
Belt - A.C.; W/55 3/4" Belt O.C. ....	C9NN 8620 A	▲9555HD
Belt - Alt. ....	D5NN 10C318 A	▲9325HD
Belt - Fan .....	D6NN 8620 A	▲9463HD
Belt - Fan & P.S. ....	D6NN 8620 A	▲9463HD

②Two Required ≧<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>8000</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
<b>1973</b>		
Belt - Fan; Feb. 1, 1973 & Newer .....	D2NN 8620 A	▲9570HD
Belt - Fan; Jan. 31, 1973 & Older .....	C7NN 8620 A	7570
Belt - W.P. & Alt.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9463HD
Belt - W.P. & Alt.; W/56 1/4" Belt O.C. ....	C9NN 10C318 C	▲9560HD
Belt - W.P. & Alt.; W/57 5/8" Belt O.C. ....	C7NN 8620 B	7570
Belt - W.P. & Gen. ....		▲9550HD
Hose - Upper; Feb. 28, 1973 & Older .....		●26612
Hose - Upper; Mar. 1, 1973 & Newer .....		●25482
Hose - Lower - Cooler To Rad. ....		●26514
Hose - Lower - Eng. To Cooler .....		20206
		or ●26501
<b>1972-1968</b>		
Belt - Fan .....	C7NN 8620 A	7570
Belt - W.P. & Alt.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9463HD
Belt - W.P. & Alt.; W/56 1/4" Belt O.C. ....	C9NN 10C318 C	▲9560HD
Belt - W.P. & Alt.; W/57 5/8" Belt O.C. ....	C7NN 8620 B	7570
Belt - W.P. & Gen. ....		▲9550HD
Hose - Upper .....		●26612
Hose - Lower - Cooler To Rad. ....		●26514
Hose - Lower - Eng. To Cooler .....		20206
		or ●26501
<b>8600</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
<b>1977-1973</b>		
Belt - A.C. ....	D3NN 19D621 B	▲9370HD
Belt - Fan .....	D2NN 8620 A	▲9570HD
Belt - W.P. & Alt. ....		▲9560HD
Hose - Upper; W/O Pipe .....		●25484
Hose - Upper - Eng. To Pipe .....		●<20957
Hose - Upper - Pipe To Pipe .....		●<20957
Hose - Upper - Pipe To Rad. ....		20431
<b>8700</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
<b>1979-1976</b>		
Belt - W.P. & Alt. ....	D6NN 8620 B	▲9585HD
<b>9000</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
<b>1973</b>		
Belt - Fan; Feb. 1973 & Newer .....	D2NN 8620 A	▲9570HD
Belt - W.P. & Alt.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9463HD
Belt - W.P. & Alt.; W/56 1/4" Belt O.C. ....	C9NN 10C318 C	▲9560HD
Belt - W.P. & Alt.; W/57 5/8" Belt O.C. ....	C7NN 8620 B	7570
Belt - W.P. & Gen. ....		▲9550HD
Hose - Upper .....		●25482
Hose - Lower - Cooler To Rad. ....		●<20206
		or ●26507
Hose - Lower - Eng. To Pipe .....		●<20046
		or ●26602
Hose - Lower - Pipe To Cooler .....		●<20357
		or ●26601
<b>1972</b>		
Belt - W.P. & Alt.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9463HD
Belt - W.P. & Alt.; W/56 1/4" Belt O.C. ....	C9NN 10C318 C	▲9560HD
Belt - W.P. & Alt.; W/57 5/8" Belt O.C. ....	C7NN 8620 B	7570
Belt - W.P. & Gen. ....		▲9550HD
Hose - Upper; Oct. 1972 & Newer .....		●25482
Hose - Upper; Sept. 1972 & Older .....		●26612
Hose - Lower - Cooler To Rad. ....		●<20206
		or ●26507
Hose - Lower - Eng. To Pipe .....		●<20046
		or ●26602
Hose - Lower - Pipe To Cooler .....		●<20357
		or ●26601
<b>1971-1969</b>		
Belt - W.P. & Alt.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9463HD
Belt - W.P. & Alt.; W/56 1/4" Belt O.C. ....	C9NN 10C318 C	▲9560HD
Belt - W.P. & Alt.; W/57 5/8" Belt O.C. ....	C7NN 8620 B	7570
Belt - W.P. & Gen. ....		▲9550HD
Hose - Upper .....		●26612

Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>9000 - Continued</b>		
<b>Ford 6-Cyl. 401 Diesel - Continued</b>		
<b>1971-1969 - Continued</b>		
Hose - Lower - Cooler To Rad. ....		●<20206
		or ●26507
Hose - Lower - Eng. To Pipe .....		●<20046
		or ●26602
Hose - Lower - Pipe To Cooler .....		●<20357
		or ●26601
<b>9600</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
<b>1976-1972</b>		
Belt - A.C. ....	D3NN 19D621 B	▲9370HD
Belt - Fan; W/57" Belt O.C.; W/25/64" Belt T.W. ....	C7NN 8620 B	7570
Belt - Fan; W/57" Belt O.C.; W/31/64" Belt T.W. ....	D2NN 8620 A	▲9570HD
Belt - W.P. & Alt. ....		▲9560HD
Hose - Upper; W/O Pipe .....		●25484
Hose - Upper - Eng. To Pipe .....		●<20957
Hose - Upper - Pipe To Pipe .....		●<20957
Hose - Upper - Pipe To Rad. ....		●<20611
<b>9700</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
<b>1979-1976</b>		
Belt - W.P. & Alt. ....	D6NN 8620 B	▲9585HD
<b>Golden Jubilee NAA</b>		
<b>Ford 4-Cyl. 134</b>		
<b>1954-1953</b>		
Belt - Fan & Gen. ....	8N 8620	TR20412
Hose - Upper .....		24220
Hose - Lower .....		●<21660
<b>TW5</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
<b>1986-1983</b>		
Belt - A.C. ....	E3NN 19D621 AA	▲9560HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....	D8NN 10C318 AA	▲9580HD
Hose - Upper .....		●25480
Hose - Lower - Eng. To Pipe .....		24428
Hose - Lower - Pipe To Rad. ....		24428
<b>TW10</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
<b>1983-1979</b>		
Belt - A.C. ....	C9NN 10C318 A	▲9555HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....	D8NN 10C318 AA	▲9580HD
<b>TW15</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
<b>1986-1983</b>		
Belt - A.C.; W/31 1/4" Belt O.C. ....	D8NN 10C318 BA	▲9309HD
Belt - A.C.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9465HD
Belt - A.C.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....	D8NN 10C318 AA	▲9580HD
Hose - Upper .....		●26611
Hose - Lower - Eng. To Pipe .....		24432
Hose - Lower - Pipe To Rad. ....		24432
<b>TW20</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
<b>1983-1979</b>		
Belt - A.C. ....	C9NN 10C318 A	▲9555HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....	D8NN 10C318 AA	▲9580HD
Hose - Upper .....		●<21379
		or ●26510
Hose - Lower - Eng. To Pipe .....		24432
Hose - Lower - Pipe To Rad. ....		24432

●<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>FORD - Continued</b>		
<b>TW25</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1986-1983		
Belt - A.C.; W/31 1/4" Belt O.C. ....	D8NN 10C318 BA	▲9309HD
Belt - A.C.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9465HD
Belt - A.C.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....	D8NN 10C318 AA	▲9580HD
Hose - Upper .....		●26611
Hose - Lower - Eng. To Pipe .....		24432
Hose - Lower - Pipe To Rad. ....		24432
<b>TW30</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1983-1979		
Belt - A.C. ....	C9NN 10C318 A	▲9555HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....	D8NN 10C318 AA	▲9580HD
<b>TW35</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1986-1983		
Belt - A.C.; W/31 1/4" Belt O.C. ....	D8NN 10C318 BA	▲9309HD
Belt - A.C.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9465HD
Belt - A.C.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....	D8NN 10C318 AA	▲9580HD
Hose - Upper .....		●26611
Hose - Lower - Eng. To Pipe .....		24432
Hose - Lower - Pipe To Rad. ....		24432
<b>FORD-NEW HOLLAND</b>		
<b>1120</b>		
<b>Shibaura 3-Cyl. 54 Diesel</b>		
1993-1987		
Belt - Fan & Alt. ....		▲9370HD
Hose - Upper .....		●25476
Hose - Lower .....		●25474
<b>1215</b>		
<b>Shibaura 3-Cyl. 54 Diesel</b>		
1998-1993		
Belt - Fan & Alt. ....		6730
Hose - Upper .....		●25152
<b>1220</b>		
<b>Shibaura 3-Cyl. 58 Diesel</b>		
1999-1987		
Belt - Fan & Alt. ....		▲9370HD
Hose - Upper .....		●25476
Hose - Lower .....		●25474
<b>1310</b>		
<b>Shibaura 3-Cyl. 58 Diesel</b>		
1986-1983		
Belt - Fan & Alt. ....		7315
Hose - Upper .....		or ●25252
		or ●25252
Hose - Lower .....		●25252
<b>1320</b>		
<b>Shibaura 3-Cyl. 77 Diesel</b>		
1998-1987		
Belt - Fan & Alt. ....		▲9370HD
Hose - Upper .....		●25476
Hose - Lower .....		●25474
<b>1510</b>		
<b>Shibaura 3-Cyl. 68 Diesel</b>		
1987-1983		
Belt - Fan & Alt. ....		7350
Hose - Upper .....		20661
		or ●25251

Application	OEM No.	Our No.
<b>FORD-NEW HOLLAND - Continued</b>		
<b>1510 - Continued</b>		
<b>Shibaura 3-Cyl. 68 Diesel - Continued</b>		
1987-1983 - Continued		
Hose - Lower .....		●25252
<b>1520</b>		
<b>Shibaura 3-Cyl. 81 Diesel</b>		
1998-1987		
Belt - Fan & Alt. ....		▲9370HD
Hose - Upper .....		●25476
Hose - Lower .....		●25474
<b>1620</b>		
<b>Shibaura 3-Cyl. 81 Diesel</b>		
1997-1992		
Belt - Fan & Alt. ....		▲9375HD
<b>1630</b>		
<b>Shibaura 3-Cyl. 81 Diesel</b>		
1999-1997		
Belt - Fan .....	86517954	AX36
<b>1715</b>		
<b>Shibaura 3-Cyl. 81 Diesel</b>		
1997-1992		
Belt - Fan & Alt. ....		▲9375HD
Hose - Upper .....		●25477
Hose - By Pass .....		●28460
<b>1720</b>		
<b>Shibaura 3-Cyl. 91 Diesel</b>		
2000-1987		
Belt - Fan & Alt. ....		▲9375HD
Hose - Upper .....		●25252
Hose - Lower .....		●25474
<b>1725</b>		
<b>Shibaura 3-Cyl. 81 Diesel</b>		
1999-1997		
Belt - Fan .....	86517954	AX36
<b>1910</b>		
<b>Shibaura 3-Cyl. 104 Diesel</b>		
1986-1983		
Belt - Fan & Alt. ....		▲9435HD
Hose - Upper .....		●25252
<b>1920</b>		
<b>Shibaura 4-Cyl. 122 Diesel</b>		
2000-1987		
Belt - Fan & Alt. ....		▲9380HD
Hose - Upper .....		●25252
Hose - Lower .....		●21752
Hose - By Pass .....		●28460
<b>1925</b>		
<b>Iveco 3-Cyl. 91 Diesel</b>		
1998-1996		
Belt - Fan .....	86517954	AX36
<b>2110</b>		
<b>Shibaura 4-Cyl. 139 Diesel</b>		
1987-1983		
Belt - Fan & Alt. ....	REMF6430	▲9440HD
Hose - Upper .....		●25478

≡<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>FORD-NEW HOLLAND - Continued</b>		
<b>2120</b>		
Shibaura 4-Cyl. 139 Diesel		
2002-1987		
Belt - Fan & Alt. ....		▲9430HD
<b>2810</b>		
Ford 3-Cyl. 158 Diesel		
1990-1983		
Belt - Fan & Alt. ....		▲9550HD
Hose - Upper .....		☞<20065
		or ●25473
<b>2910</b>		
Ford 3-Cyl. 175 Diesel		
1990-1983		
Belt - Fan & Alt. ....	D3NN 10C318 C	▲9555HD
Hose - Upper .....		☞<20065
<b>3010S</b>		
Iveco 3-Cyl. 165 Diesel		
2003-1996		
Belt - Fan .....	4796327	7450
<b>3230</b>		
Ford 3-Cyl. 192 Diesel		
1994-1990		
Belt - Fan & Alt. ....	D3NN 10C318 C	▲9555HD
Hose - Upper .....		☞<20065
		or ●25251
<b>3415</b>		
Ford 4-Cyl. 135 Diesel		
2002-1993		
Belt - Fan & Alt. ....		▲9370HD
Hose - By Pass .....		☞<28460
<b>3430</b>		
Ford 3-Cyl. 192 Diesel		
1998-1990		
Belt - Fan & Alt. ....	D3NN 10C318 C	▲9555HD
Hose - Upper .....		☞<20065
		or ●25251
<b>3830</b>		
Ford 3-Cyl. 165 Diesel		
1999-1992		
Belt - Fan & Alt. ....		7450
Hose - Lower - Eng. To Pipe .....		24224
<b>3910</b>		
Ford 3-Cyl. 192 Diesel		
1989-1983		
Belt - Fan & Alt. ....		▲9550HD
Hose - Upper .....		☞<20065
		or ●25473
<b>3930</b>		
Ford 3-Cyl. 192 Diesel		
2001-1996		
Belt - Fan & Alt. ....	D3NN 10C318 C	▲9555HD
Hose - Upper .....		☞<20065
		or ●25251
<b>Ford 3-Cyl. 201 Diesel</b>		
1995-1990		
Belt - Fan & Alt. ....	D3NN 10C318 C	▲9555HD
Hose - Upper .....		☞<20065
		or ●25251
<b>4030N</b>		
Ford 3-Cyl. 179 Diesel		
1997-1992		
Belt - A.C. ....	9966451	▲9600HD

Application	OEM No.	Our No.
<b>FORD-NEW HOLLAND - Continued</b>		
<b>4030N - Continued</b>		
Ford 3-Cyl. 179 Diesel - Continued		
1997-1992 - Continued		
Belt - Fan .....	4809680	7445
Hose - Upper .....		24220
Hose - Lower .....		☞<21660
<b>4230N</b>		
Ford 4-Cyl. 220 Diesel		
1997-1992		
Belt - A.C. ....	9966451	▲9600HD
Belt - Fan .....	4796327	7450
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>4430N</b>		
Ford 4-Cyl. 238 Diesel		
1998-1992		
Belt - A.C. ....	9966451	▲9600HD
Belt - Fan .....	4796327	7450
<b>4430V</b>		
Ford 4-Cyl. 220 Diesel		
1998-1997		
Belt - A.C. ....	9966451	▲9600HD
Belt - Fan .....	4796327	7450
<b>4610</b>		
Ford 3-Cyl. 201 Diesel		
1990-1982		
Belt - Fan & Alt. ....		▲9555HD
Hose - Upper .....		☞<20065
<b>4630</b>		
Ford 3-Cyl. 192 Diesel		
2002-1996		
Belt - Fan & Alt. ....	D3NN 10C318 C	▲9555HD
Hose - Upper .....		☞<20065
		or ●25251
<b>Ford 3-Cyl. 201 Diesel</b>		
1995-1989		
Belt - Fan & Alt. ....	D3NN 10C318 C	▲9555HD
Hose - Upper .....		☞<20065
		or ●25251
<b>4835</b>		
Fiat 4-Cyl. 220 Diesel		
1999-1996		
Belt - A.C. ....	5140009	7405
Belt - Alt. ....	4796327	7450
Belt - Fan .....	5140010	7425
<b>5030</b>		
Ford 4-Cyl. 256 Diesel		
1999-1992		
Belt - Fan & Alt. ....		▲9560HD
Hose - Upper .....		21660
		or ●25473
Hose - Lower .....		☞<20145
		or ●26502
<b>5530</b>		
Ford 4-Cyl. 220 Diesel		
1996-1992		
Belt - Fan & Alt. ....		▲9463HD
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>5610</b>		
Ford 4-Cyl. 256 Diesel		
1993-1982		
Belt - A.C.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9465HD

☞<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>FORD-NEW HOLLAND - Continued</b>		
<b>5610 – Continued</b>		
<b>Ford 4-Cyl. 256 Diesel – Continued</b>		
1993–1982 – Continued		
Belt - A.C.; W/56 1/4" Belt O.C.		▲9560HD
Belt - Alt.	D5NN 10C318 A	▲9325HD
Belt - Fan	D6NN 8620 A	▲9463HD
Belt - Fan & Alt.		▲9550HD
Belt - Fan To Alt.		▲9313HD
Hose - Upper		20065
	or	●25473
<b>5610S</b>		
<b>Genesis 4-Cyl. 268 Diesel</b>		
1996–1993		
Belt - Fan	87800129	▲9560HD
<b>Genesis 4-Cyl. 304 Diesel</b>		
2003–1996		
Belt - Fan	87800129	▲9560HD
<b>5635</b>		
<b>Fiat 4-Cyl. 238 Diesel</b>		
1999–1996		
Belt - A.C.	5140009	7405
Belt - Alt.	4796327	7450
Belt - Fan	5140010	7425
<b>5640</b>		
<b>Ford 4-Cyl. 268 Diesel</b>		
1997–1991		
Belt - Fan & Alt.	F0NN 8620 FA	▲K060875HD
Tensioner Assy.	87801689	38672
Hose - Upper		20137
<b>5900</b>		
<b>Ford 4-Cyl. 256 Diesel</b>		
1991–1985		
Belt - Fan & Alt.		▲9550HD
Hose - Upper		≧21794
	or	●25473
<b>6530</b>		
<b>Fiat 4-Cyl. 238 Diesel</b>		
1997–1992		
Belt - Fan & Alt.; W/45 5/8" Belt O.C.		7450
Hose - Lower - Eng. To Pipe		24222
Hose - Lower - Pipe To Rad.		24222
<b>6610</b>		
<b>Ford 4-Cyl. 268 Diesel</b>		
1993–1981		
Belt - A.C.	E3NN 19D621 AA	▲9560HD
Belt - Fan		▲9451HD
Belt - Fan & Alt.		▲9540HD
Belt - Fan To Alt.	D5NN 10C318 C	▲9305HD
Hose - Upper		≧20065
	or	●25473
<b>6610S</b>		
<b>Genesis 4-Cyl. 304 Diesel</b>		
2003–1994		
Belt - Fan	87800129	▲9560HD
<b>6635</b>		
<b>Fiat 4-Cyl. 238 Diesel</b>		
1999–1996		
Belt - A.C.	5140009	7405
Belt - Alt.	4796327	7450
Belt - Fan	5140010	7425

Application	OEM No.	Our No.
<b>FORD-NEW HOLLAND - Continued</b>		
<b>6640</b>		
<b>Ford 4-Cyl. 304 Diesel</b>		
1997–1991		
Belt - Serpentine; W/A.C.	F3NN 8620 AA	▲K061005HD
Belt - Serpentine; W/O A.C.		▲K060875HD
Tensioner Assy.	87801689	38672
Hose - Upper		≧20137
<b>7010</b>		
<b>Genesis 4-Cyl. 304 Diesel</b>		
2003–1995		
Belt - Fan & Alt.	A53	A53
<b>7530</b>		
<b>Fiat 6-Cyl. 331 Diesel</b>		
1996–1991		
Belt - Fan & Alt.		③7435
Hose - Lower - Eng. To Pipe		24222
Hose - Lower - Pipe To Rad.		24222
<b>7610</b>		
<b>Ford 4-Cyl. 268 Diesel</b>		
1991–1981		
Belt - A.C.		▲9560HD
Belt - Fan		▲9463HD
Belt - Fan To Alt.; W/30 7/8" Belt O.C.	D5NN 10C318 C	▲9305HD
Belt - Fan To Alt.; W/31 3/4" Belt O.C.		▲9313HD
Belt - Fan To Alt.; W/32 3/4" Belt O.C.		▲9325HD
Belt - Fan To Alt.; W/46 1/4" Belt O.C.	D5NN 10C318 C	▲9463HD
Hose - Upper		≧20065
	or	●25473
<b>7610S</b>		
<b>Genesis 4-Cyl. 304 Diesel</b>		
2003–1994		
Belt - Fan	87800129	▲9560HD
<b>7635</b>		
<b>Fiat 4-Cyl. 238 Diesel</b>		
1999–1996		
Belt - A.C.	5140009	7405
Belt - Alt.	4796327	7450
Belt - Fan	5140010	7425
<b>7710</b>		
<b>Ford 4-Cyl. 268 Diesel</b>		
1991–1981		
Belt - A.C.		▲9560HD
Belt - Fan		▲9463HD
Belt - Fan To Alt.; W/30 7/8" Belt O.C.	D5NN 10C318 C	▲9305HD
Belt - Fan To Alt.; W/31 3/4" Belt O.C.		▲9313HD
Belt - Fan To Alt.; W/32 3/4" Belt O.C.		▲9325HD
Belt - Fan To Alt.; W/46 1/4" Belt O.C.	D5NN 10C318 C	▲9463HD
Hose - Upper		≧21794
	or	●25477
<b>7740</b>		
<b>Ford 4-Cyl. 304 Diesel</b>		
1997–1991		
Belt - Serpentine; W/A.C.	F3NN 8620 AA	▲K061005HD
Belt - Serpentine; W/O A.C.		▲K060875HD
Tensioner Assy.	87801689	38672
Hose - Upper		≧20137
<b>7810</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1991–1978		
Belt - Fan		▲9451HD
Belt - Fan To Alt.	E4NN 10C318 AA	▲9313HD
Hose - Upper		20357
	or	●26602
Hose - Lower - Eng. To Pipe		≧21194
Hose - Lower - Pipe To Rad.		≧21194

③Three Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>FORD-NEW HOLLAND - Continued</b>		
<b>7840</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1998-1997		
Tensioner Assy. ....	87801689	38672
1996		
Hose - Upper .....		●25477
1995-1991		
Belt - Fan; W/A.C. ....	87309963	▲K061005HD
Belt - Fan; W/O A.C. ....	87316556	▲K060870HD
Tensioner Assy. ....	87801689	38672
Hose - Upper .....		●25477
<b>8010</b>		
<b>Genesis 6-Cyl. 456 Diesel</b>		
2003-1996		
Belt - Fan & Alt. ....	A53	A53
<b>8160</b>		
<b>Genesis 6-Cyl. 456 Diesel</b>		
1999-1996		
Belt - Fan, Alt. & A.C. ....	87800858	▲K080774HD
<b>8210</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1991-1982		
Belt - W.P. & Alt. ....		▲9580HD
Hose - Lower .....		②24248
<b>8240</b>		
<b>Ford 6-Cyl. 456 Diesel</b>		
1996-1991		
Belt - Fan; W/A.C. ....	87309963	▲K061005HD
Belt - Fan; W/O A.C. ....	87316556	▲K060870HD
Tensioner Assy. ....	87801689	38672
Hose - Upper .....		●25478
<b>8260</b>		
<b>Genesis 6-Cyl. 456 Diesel</b>		
1999-1996		
Belt - Fan, Alt. & A.C. ....	87800858	▲K080774HD
<b>8340</b>		
<b>Ford 6-Cyl. 456 Diesel</b>		
1996-1991		
Belt - Fan; W/A.C. ....	87309963	▲K061005HD
Belt - Fan; W/O A.C. ....	87316556	▲K060870HD
Tensioner Assy. ....	87801689	38672
Hose - Upper .....		●25477
<b>8360</b>		
<b>Genesis 6-Cyl. 456 Diesel</b>		
1999-1996		
Belt - Fan, Alt. & A.C. ....	87800858	▲K080774HD
<b>8530</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1995-1989		
Belt - A.C. ....		▲9555HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....		▲9585HD
Hose - Upper .....		②20046
		or ●26611
Hose - Lower - Eng. To Pipe .....		24432
Hose - Lower - Pipe To Rad. ....		24432
<b>8560</b>		
<b>Genesis 6-Cyl. 456 Diesel</b>		
1999-1996		
Belt - Fan, Alt. & A.C. ....	87800858	▲K080774HD

Application	OEM No.	Our No.
<b>FORD-NEW HOLLAND - Continued</b>		
<b>8630</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1995-1989		
Belt - A.C. ....		▲9555HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....		▲9585HD
Hose - Upper .....		②20046
		or ●26611
Hose - Lower - Eng. To Pipe .....		24432
Hose - Lower - Pipe To Rad. ....		24432
<b>8670</b>		
<b>Genesis 6-Cyl. 456 Diesel</b>		
2002-1993		
Belt - Fan, Alt. & A.C. ....	86013678	▲K081000HD
Hose - By Pass .....		24224
<b>8730</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1995-1989		
Belt - A.C. ....		▲9555HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....		▲9585HD
Hose - Upper .....		②20046
		or ●26611
Hose - Lower - Eng. To Pipe .....		24432
Hose - Lower - Pipe To Rad. ....		24432
<b>8770</b>		
<b>Genesis 6-Cyl. 456 Diesel</b>		
2002-1993		
Belt - Fan, Alt. & A.C. ....	86013678	▲K081000HD
<b>8830</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1995-1989		
Belt - A.C. ....		▲9555HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....		▲9585HD
Hose - Upper .....		②20046
Hose - Lower .....		②24248
<b>8870; 8970</b>		
<b>Genesis 6-Cyl. 456 Diesel</b>		
2002-1993		
Belt - Fan, Alt. & A.C. ....	86013678	▲K081000HD
Hose - By Pass .....		24224
<b>9682</b>		
<b>Cummins N14 Diesel</b>		
1999		
Belt - A.C. ....	86514599	▲9390HD
Belt - W.P. ....	86514607	▲K060435HD
1998		
Belt - A.C. ....	86514599	▲9390HD
Belt - Alt.; Sept. 7, 1998 & Older .....	9707244	②▲9451HD
Belt - Fan; Sept. 7, 1998 & Older .....	86514991	②TR28437
Belt - W.P. ....	86514607	▲K060435HD
1997-1995		
Belt - A.C. ....	86514599	▲9390HD
Belt - Alt. ....	9707244	②▲9451HD
Belt - Fan .....	86514991	②TR28437
Belt - W.P. ....	86514607	▲K060435HD
<b>TW5</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1990-1987		
Belt - A.C. ....	E3NN 19D621 AA	▲9560HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....	D8NN 10C318 AA	▲9580HD
Hose - Upper .....		●25480
Hose - Lower - Eng. To Pipe .....		24428
Hose - Lower - Pipe To Rad. ....		24428

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>FORD-NEW HOLLAND - Continued</b>		
<b>TW15; TW25; TW35</b>		
<b>Ford 6-Cyl. 401 Diesel</b>		
1990-1987		
Belt - A.C.; W/31 1/4" Belt O.C. ....	D8NN 10C318 BA	▲9309HD
Belt - A.C.; W/46 3/4" Belt O.C. ....	C9NN 10C318 B	▲9465HD
Belt - A.C.; W/56 1/4" Belt O.C. ....		▲9560HD
Belt - Fan .....	D6NN 8620 B	▲9585HD
Belt - W.P. & Alt. ....	D8NN 10C318 AA	▲9580HD
Hose - Upper .....		●26611
Hose - Lower - Eng. To Pipe .....		24432
Hose - Lower - Pipe To Rad. ....		24432
<b>FORDSON</b>		
<b>Dexta</b>		
<b>Perkins 3-Cyl. 144 Diesel</b>		
1961-1958		
Belt - Fan .....		▲9451HD
<b>Major</b>		
<b>Ford 4-Cyl. 220 Diesel</b>		
1958-1953		
Belt - Fan & Gen.; W/45 1/4" Belt O.C. ....		▲9451HD
Belt - Fan & Gen.; W/49 3/4" Belt O.C. ....		TR28492
Belt - P.S. ....		▲9451HD
<b>Power Major</b>		
<b>Ford 4-Cyl. 220 Diesel</b>		
1961-1958		
Belt - Fan & Gen.; W/45 1/4" Belt O.C. ....		▲9451HD
Belt - Fan & Gen.; W/49 3/4" Belt O.C. ....		TR28492
Belt - P.S. ....		▲9451HD
<b>Super Dexta</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1964-1961		
Belt - Fan & Gen. ....	E1ADKN 8620 C	▲9451HD
<b>Super Major</b>		
<b>Ford 4-Cyl. 199</b>		
1964-1961		
Hose - Upper .....		≠20957
		or ●26501
<b>Ford 4-Cyl. 220 Diesel</b>		
1964-1961		
Belt - Fan & Gen.; W/45 1/4" Belt O.C. ....		▲9451HD
Belt - Fan & Gen.; W/49 3/4" Belt O.C. ....		TR28492
Belt - P.S. ....		▲9451HD
Hose - Upper .....		≠20957
		or ●26501
<b>HESSTON</b>		
<b>45-66</b>		
<b>Fiat 3-Cyl. 165 Diesel</b>		
1991-1986		
Belt - Fan & Alt. ....		7440
Hose - Upper .....		●26501
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>55-46</b>		
<b>Fiat 3-Cyl. 165 Diesel</b>		
1989-1987		
Belt - Fan & Alt. ....	2604796324	7455
<b>55-56</b>		
<b>Fiat 3-Cyl. 165 Diesel</b>		
1991-1984		
Belt - Fan & Alt. ....	2604796324	7455
Hose - Lower .....		②24224

Application	OEM No.	Our No.
<b>HESSTON - Continued</b>		
<b>55-76</b>		
<b>Fiat 3-Cyl. 165 Diesel</b>		
1990-1981		
Belt - Fan & Alt. ....		7435
Hose - Lower .....		②24224
<b>60-66</b>		
<b>Fiat 3-Cyl. 179 Diesel</b>		
1991-1984		
Belt - Fan & Alt.; W/44 5/8" Belt O.C. ....		7445
Belt - Fan & Alt.; W/45 5/8" Belt O.C. ....		7455
<b>65-46</b>		
<b>Fiat 4-Cyl. 220 Diesel</b>		
1992-1987		
Belt - Fan & Alt. ....	2604796324	7455
<b>65-56</b>		
<b>Fiat 4-Cyl. 220 Diesel</b>		
1992-1987		
Belt - Fan & Alt. ....	2604796324	7455
Hose - Lower .....		②24224
<b>70-66</b>		
<b>Fiat 4-Cyl. 220 Diesel</b>		
1992-1984		
Belt - Fan & Alt.; W/44 5/8" Belt O.C. ....		7445
Belt - Fan & Alt.; W/45 5/8" Belt O.C. ....		7455
Hose - Upper .....		●26501
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>70-90</b>		
<b>Fiat 4-Cyl. 220 Diesel</b>		
1991-1984		
Belt - A.C. ....		7405
Belt - Fan .....		7430
Belt - Fan & Alt. ....		7470
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>80-66</b>		
<b>Fiat 4-Cyl. 238 Diesel</b>		
1991-1984		
Belt - Fan & Alt. ....		7445
Hose - Upper .....		●26501
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>80-76DT</b>		
<b>Fiat 4-Cyl. 238 Diesel</b>		
1992-1989		
Belt - Fan & Alt. ....		7445
Hose - Lower .....		②24224
<b>80-90</b>		
<b>Fiat 4-Cyl. 238 Diesel</b>		
1992-1984		
Belt - Fan .....		7425
Belt - Fan & Alt. ....		7465
Belt - Fan To A.C. ....		7405
Hose - Upper .....		●26501
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>90-90</b>		
<b>Fiat 5-Cyl. 298 Diesel</b>		
1992-1984		
Belt - Fan & Alt. ....		7455
Hose - Upper .....		●26502
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224

②Two Required ≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>HESSTON - Continued</b>		
<b>100-90</b>		
<b>Fiat 6-Cyl. 331 Diesel</b>		
1992-1984		
Belt - Fan & Alt. ....	2604796324	7455
Hose - Upper .....		●26501
Hose - Lower .....		②24224
<b>130-90</b>		
<b>Fiat 6-Cyl. 358 Diesel</b>		
1991-1984		
Belt - Fan & A.C. ....		②7580
Belt - Fan & Alt. ....		7465
Hose - Upper .....		●26502
Hose - Lower .....		②24224
<b>160-90</b>		
<b>Fiat 6-Cyl. 494 Diesel</b>		
1992-1984		
Belt - Alt. ....		▲9451HD
Belt - Fan .....		②▲9495HD
Belt - Fan & Alt. ....		②7530
Belt - Fan To A.C.; W/Dual Belts .....		②7673
Belt - Fan To A.C.; W/Single Belt .....		▲9350HD
Hose - Upper .....		●26506
Hose - Lower - Cooler To Rad. ....		24224
Hose - Lower - Eng. To Cooler .....		24224
Hose - By Pass .....		24228
<b>180-90</b>		
<b>Fiat 6-Cyl. 494 Diesel</b>		
1992-1984		
Belt - Alt. ....		▲9451HD
Belt - Fan .....		②▲9495HD
Belt - Fan & Alt. ....		②7530
Belt - Fan To A.C.; W/Dual Belts .....		②7673
Belt - Fan To A.C.; W/Single Belt .....		▲9350HD
Hose - Upper .....		●26505
Hose - Lower .....		24228
Hose - By Pass .....		24228
<b>580</b>		
<b>Fiat 3-Cyl. 168 Diesel</b>		
1984-1981		
Belt - Fan & Alt. ....		7460
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>666</b>		
<b>Fiat 4-Cyl. 211 Diesel</b>		
1990-1983		
Belt - Fan & Alt. ....		7445
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>680</b>		
<b>Fiat 4-Cyl. 211 Diesel</b>		
1984-1980		
Belt - Fan & Alt. ....		7460
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>766</b>		
<b>Fiat 4-Cyl. 224 Diesel</b>		
1990-1983		
Belt - Fan & Alt. ....		7445
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>980</b>		
<b>Fiat 6-Cyl. 316 Diesel</b>		
1984-1981		
Belt - Fan & A.C. ....		②7570
Belt - Fan & Alt. ....		7460
Hose - Lower - Eng. To Pipe .....		24224

Application	OEM No.	Our No.
<b>HESSTON - Continued</b>		
<b>980 - Continued</b>		
<b>Fiat 6-Cyl. 316 Diesel - Continued</b>		
1984-1981 - Continued		
Hose - Lower - Pipe To Rad. ....		24224
<b>1380DT</b>		
<b>Fiat 6-Cyl. 335 Diesel</b>		
1984-1981		
Belt - Fan & A.C. ....	5112185	②7565
Belt - Fan & Alt. ....		7465
Hose - Upper .....		●26611
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>1580</b>		
<b>Fiat 6-Cyl. 494 Diesel</b>		
1984-1981		
Belt - A.C. ....		7619
Belt - Fan & Alt. ....		②7530
Hose - Lower - Eng. To Pipe .....		24230
Hose - Lower - Pipe To Rad. ....		≈20520
<b>1880</b>		
<b>Fiat 6-Cyl. 494 Diesel</b>		
1984-1981		
Belt - A.C. ....		②7630
Belt - Fan & Alt. ....		②7530
Hose - Upper .....		●26505
<b>HESSTON-FIAT</b>		
<b>60-75CV</b>		
<b>Hesston-Fiat 8035.05 Diesel</b>		
1993-1990		
Belt - Fan & Alt. ....		7440
Hose - Lower .....		②24224
<b>70-65CM</b>		
<b>Hesston-Fiat 8045.06 Diesel</b>		
1991-1984		
Belt - Fan & Alt.; W/44 5/8" Belt O.C. ....		7445
Belt - Fan & Alt.; W/45 5/8" Belt O.C. ....		7455
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>70-75C</b>		
<b>Hesston-Fiat 8055.05 Diesel</b>		
1993-1990		
Belt - Fan & Alt. ....	2604796324	7455
Hose - Lower .....		②24224
<b>70-75CM</b>		
<b>Hesston-Fiat 8045.06 Diesel</b>		
1993-1990		
Belt - Fan & Alt. ....	2604796324	7455
Hose - Lower .....		②24224
<b>95-55C</b>		
<b>Hesston-Fiat 8055.04 Diesel</b>		
1993-1983		
Belt - Fan & Alt. ....		7455
Hose - Upper .....		●26502
Hose - Lower .....		②24224
<b>IMT</b>		
<b>536</b>		
<b>IMR 3-Cyl. 152 Diesel</b>		
1990-1989		
Belt - Fan & Alt. ....		7430
Hose - Upper - Eng. To Pipe .....		≈21145
		or ●25472
Hose - Upper - Eng. To W.P. ....		24220
Hose - Lower .....		②24220

②Two Required ≈Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>IMT - Continued</b>		
<b>539</b>		
<b>IMR 3-Cyl. 152 Diesel</b>		
1993-1989		
Belt - Fan & Alt. ....		7430
Hose - Upper - Eng. To Pipe .....		≧21145
	or	●25472
Hose - Upper - Eng. To W.P. ....		24220
Hose - Lower .....		②24220
<b>542</b>		
<b>IMR 3-Cyl. 152 Diesel</b>		
1993-1986		
Belt - Fan & Alt. ....		7430
Hose - Upper - Eng. To Pipe .....		≧21145
	or	●25472
Hose - Upper - Eng. To W.P. ....		24220
Hose - Lower .....		②24220
<b>549DV</b>		
<b>IMR 3-Cyl. 152 Diesel</b>		
1992-1991		
Belt - Fan & Alt. ....		7430
<b>560</b>		
<b>IMR 4-Cyl. 203 Diesel</b>		
1993-1986		
Belt - Fan & Alt. ....		▲9463HD
Hose - Upper .....		≧21942
Hose - Lower .....		②24222
<b>565</b>		
<b>IMR 4-Cyl. 203 Diesel</b>		
1993-1985		
Belt - Fan & Alt. ....		▲9463HD
<b>577DV</b>		
<b>IMR 4-Cyl. 248 Diesel</b>		
1993-1987		
Belt - Fan & Alt. ....		▲9510HD
Hose - Upper .....		●25257
Hose - Lower .....		●25476
<b>5136</b>		
<b>IMR 6-Cyl. 354 Diesel</b>		
1991-1989		
Belt - Alt. ....		▲9451HD
Belt - Fan & A.C. ....		▲9600HD
Hose - Lower - Eng. To Pipe .....		≧20206
Hose - Lower - Pipe To Rad. ....		24432
<b>INTERNATIONAL HARVESTER</b>		
<b>70 Hydro</b>		
<b>IH 6-Cyl. 291</b>		
1976-1973		
Belt - Fan; Ser. No. 11050 & Before .....	403617R1	▲9470HD
Belt - Fan; Ser. No. 11051 & After .....		▲9570HD
Belt - W.P. & Alt. ....	530186R1	▲9640HD
Hose - Lower .....		●26510
<b>IH 6-Cyl. 312 Diesel</b>		
1976-1973		
Belt - Fan .....	403617R1	▲9470HD
Belt - W.P. & Alt. ....	65999C1	TR24638
Hose - By Pass .....		24220
<b>84 Hydro</b>		
<b>IH 4-Cyl. 246 Diesel</b>		
1985-1978		
Belt - Fan & Alt. ....	527470R1	▲9605HD

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>86 Hydro</b>		
<b>IH 6-Cyl. 291</b>		
1981-1976		
Belt - Fan; Ser. No. 11050 & Before .....	403617R1	▲9470HD
Belt - Fan; Ser. No. 11051 & After .....		▲9570HD
Belt - W.P. & Alt. ....	530186R1	▲9640HD
Hose - Lower .....		●26510
<b>IH 6-Cyl. 312 Diesel</b>		
1981-1976		
Belt - Fan .....	403617R1	▲9470HD
Belt - W.P. & Alt. ....	65999C1	TR24638
Hose - By Pass .....		24220
<b>100</b>		
<b>IH 4-Cyl. 123</b>		
1956-1955		
Belt - Fan; Ser. No. 501 Thru 65000 .....	60712D	TR26353
Belt - Fan & Gen.; Ser. No. 65001 & After ...	367697R1	7417
Belt - Gen.; Ser. No. 501 Thru 65000 .....	52318DA	9279
Hose - Upper .....		24238
Hose - Lower .....		24232
<b>100 Farmall</b>		
<b>IH 4-Cyl. 123</b>		
1956-1954		
Belt - Fan; Ser. No. 501 Thru 65000 .....	60712D	TR26353
Belt - Fan & Gen.; Ser. No. 65001 & After ...	367697R1	7417
Belt - Gen.; Ser. No. 501 Thru 65000 .....	52318DA	9279
<b>100 Hydro</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1976-1973		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan & Alt. ....	537072R91	②TR22648
Belt - W.P. & Alt. ....	532746R1	TR22648
Hose - Upper .....		●26516
Hose - Lower .....		24936
Hose - By Pass .....		≧20945
<b>130; 130 Farmall</b>		
<b>IH 4-Cyl. 123</b>		
1958-1956		
Belt - Fan; Ser. No. 501 Thru 65000 .....	60712D	TR26353
Belt - Fan & Gen.; Ser. No. 65001 & After ...	367697R1	7417
Belt - Gen.; Ser. No. 501 Thru 65000 .....	52318DA	9279
Hose - Upper .....		24238
Hose - Lower .....		24232
<b>140</b>		
<b>IH 4-Cyl. 123</b>		
1981-1958		
Belt - Fan; Ser. No. 501 Thru 65000 .....	60712D	TR26353
Belt - Fan & Gen.; Ser. No. 65001 & After ...	367697R1	7417
Belt - Gen.; Ser. No. 501 Thru 65000 .....	52318DA	9279
Hose - Upper .....		24222
Hose - By Pass .....		28439
<b>140 Farmall</b>		
<b>IH 4-Cyl. 123</b>		
1970-1958		
Belt - Fan; Ser. No. 501 Thru 65000 .....	60712D	TR26353
Belt - Fan & Gen.; Ser. No. 65001 & After ...	367697R1	7417
Belt - Gen.; Ser. No. 501 Thru 65000 .....	52318DA	9279
Hose - Upper .....		24222
Hose - By Pass .....		28439
<b>186 Hydro</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1981-1976		
Belt - A.C. ....	874097C1	▲9395HD
Belt - Fan & Alt.; W/A.C. ....	532746R1	TR22648
Belt - Fan & Alt.; W/O A.C. ....	532746R1	②TR22648
Hose - Upper .....		●26516
Hose - Lower .....		●26534

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>200 Farmall</b>		
<b>IH 4-Cyl. 123</b>		
1956-1954		
Belt - Fan; Ser. No. 501 Thru 65000 .....	60712D	TR26353
Belt - Fan & Gen.; Ser. No. 65001 & After ...	367697R1	7417
Belt - Gen.; Ser. No. 501 Thru 65000 .....	52318DA	9279
Hose - Upper .....		24238
Hose - Lower .....		24232
<b>230 Farmall</b>		
<b>IH 4-Cyl. 123</b>		
1958-1956		
Belt - Fan; Ser. No. 501 Thru 65000 .....	60712D	TR26353
Belt - Fan & Gen.; Ser. No. 65001 & After ...	367697R1	7417
Belt - Gen.; Ser. No. 501 Thru 65000 .....	52318DA	9279
Hose - Upper .....		24238
Hose - Lower .....		24232
<b>234</b>		
<b>Mitsubishi 3-Cyl. 52 Diesel</b>		
1988-1982		
Belt - Fan .....	676622R1	7370
<b>240; 240 Farmall</b>		
<b>IH 4-Cyl. 123</b>		
1962-1958		
Belt - Fan; Ser. No. 501 Thru 65000 .....	60712D	TR26353
Belt - Fan & Gen.; Ser. No. 65001 & After ...	367697R1	7417
Belt - Gen.; Ser. No. 501 Thru 65000 .....	52318DA	9279
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24222
<b>244</b>		
<b>Mitsubishi 3-Cyl. 60 Diesel</b>		
1985-1982		
Belt - Fan & Alt. ....	MD007528	7370
Hose - Upper .....		●25251
Hose - By Pass .....		26239
<b>254</b>		
<b>Mitsubishi 3-Cyl. 65 Diesel</b>		
1985-1982		
Belt - Fan & Alt. ....	MD007528	7370
Hose - Upper .....		●25251
<b>274</b>		
<b>Nissan 3-Cyl. 99 Diesel</b>		
1984-1979		
Hose - Upper .....		●25474
<b>284</b>		
<b>Mazda 4-Cyl. 71</b>		
1984-1976		
Belt - Fan & Alt. ....		▲9390HD
Hose - Upper .....		⊃21794
Hose - Lower .....		⊃21794
		or ●25477
<b>300 Farmall</b>		
<b>IH 4-Cyl. 169</b>		
1956-1954		
Belt - Fan .....	48032DA	TR24379
Belt - Gen. ....	362828R1	▲9330HD
Hose - Upper .....		24228
Hose - Lower .....		●25476
<b>IH 4-Cyl. 169 LPG</b>		
1956-1954		
Belt - Fan .....	48032DA	TR24379
Belt - Gen. ....	362828R1	▲9330HD
Hose - Upper .....		24228
Hose - Lower .....		●25476

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>300 Utility</b>		
<b>IH 4-Cyl. 169</b>		
1956-1955		
Belt - Fan .....	48032DA	TR24379
Belt - Gen. ....	362828R1	▲9330HD
Hose - Upper .....		24228
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>IH 4-Cyl. 169 LPG</b>		
1956-1955		
Belt - Fan .....	48032DA	TR24379
Belt - Gen. ....	362828R1	▲9330HD
Hose - Upper .....		24228
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>330</b>		
<b>IH 4-Cyl. 135</b>		
1958-1957		
Belt - Fan & Gen. ....	367697R1	7417
Hose - Lower .....		24224
Hose - By Pass .....		24224
<b>340</b>		
<b>IH 4-Cyl. 135</b>		
1963-1958		
Belt - Fan & Gen. ....	367697R1	7417
Hose - Upper .....		24222
Hose - Lower .....		24220
Hose - By Pass .....		24224
<b>IH 4-Cyl. 166 Diesel</b>		
1963-1958		
Belt - Fan & Gen. ....	315969R1	▲9490HD
Hose - Lower; W/1 1/2" I.D. Hose .....		24224
Hose - Lower; W/2" I.D. Hose .....		24232
Hose - By Pass .....		20338
<b>340 Farmall</b>		
<b>IH 4-Cyl. 135</b>		
1963-1958		
Belt - Fan & Gen. ....	367697R1	7417
<b>350 Farmall</b>		
<b>IH 4-Cyl. 175</b>		
1958-1956		
Belt - Fan .....	48032DA	TR24379
Belt - Gen. ....	362828R1	▲9330HD
Hose - Upper .....		24228
Hose - Lower .....		●25476
<b>IH 4-Cyl. 175 LPG</b>		
1958-1956		
Belt - Fan .....	48032DA	TR24379
Belt - Gen. ....	362828R1	▲9330HD
Hose - Upper .....		24228
Hose - Lower .....		●25476
<b>350 Utility</b>		
<b>Continental 4-Cyl. 193 Diesel</b>		
1958-1956		
Belt - Fan .....	48032DA	TR24379
Belt - Gen. ....	362828R1	▲9330HD
Hose - Upper .....		24228
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>IH 4-Cyl. 175</b>		
1958-1956		
Belt - Fan .....	48032DA	TR24379
Belt - Gen. ....	362828R1	▲9330HD
Hose - Upper .....		24228
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224

⊃Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>350 Utility – Continued</b>		
<b>IH 4-Cyl. 175 LPG</b>		
1958-1956		
Belt - Fan .....	48032DA	TR24379
Belt - Gen. ....	362828R1	▲9330HD
Hose - Upper .....		24228
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>350D Farmall</b>		
<b>Continental 4-Cyl. 193 Diesel</b>		
1958-1956		
Belt - Fan & Gen. ....	143441R2	▲9420HD
Hose - Upper .....		24228
Hose - Lower .....		●25476
<b>354</b>		
<b>IH 4-Cyl. 143</b>		
1975-1972		
Belt - Fan; W/34 3/4" Belt O.C. ....	376371R1	TR22344
Belt - Fan; W/35 1/2" Belt O.C. ....		TR22350
Belt - Gen. ....	399480R1	▲9309HD
<b>384</b>		
<b>IH 4-Cyl. 154 Diesel</b>		
1982-1978		
Belt - Fan .....	709502R1	TR22350
Belt - Fan & Alt. ....	3119750R1	7318
<b>400 Farmall</b>		
<b>IH 4-Cyl. 264</b>		
1956-1954		
Belt - Fan .....	16131DA	TR28454
Belt - Gen. ....	49341D	▲9335HD
Belt - P.S. ....	363197R2	TR30506
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
Hose - By Pass .....		24224
<b>IH 4-Cyl. 264 Diesel</b>		
1956-1954		
Belt - Fan .....	277448R1	TR30467
Belt - Gen. ....	52318DA	9279
<b>IH 4-Cyl. 264 LPG</b>		
1956-1954		
Belt - Fan .....	16131DA	TR28454
Belt - Gen. ....	49341D	▲9335HD
Belt - P.S. ....	363197R2	TR30506
<b>404</b>		
<b>IH 4-Cyl. 135</b>		
1968-1960		
Belt - Fan & Gen.; W/43 1/8" Belt O.C. ....	387920R1	7425
Belt - Fan & Gen.; W/43 5/8" Belt O.C. ....	403580R1	7430
<b>404 Farmall</b>		
<b>IH 4-Cyl. 135</b>		
1967-1961		
Belt - Fan & Gen.; W/43 1/8" Belt O.C. ....	387920R1	7425
Belt - Fan & Gen.; W/43 5/8" Belt O.C. ....	403580R1	7430
Hose - Lower; W/1 3/8" I.D. Hose .....		24222
Hose - Lower; W/2" I.D. Hose .....		24232
Hose - By Pass .....		28439
<b>424</b>		
<b>IH 4-Cyl. 146</b>		
1967-1964		
Belt - Fan & Gen.; W/43 1/8" Belt O.C. ....	387920R1	7425
Belt - Fan & Gen.; W/43 5/8" Belt O.C. ....	403580R1	7430

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>424 – Continued</b>		
<b>IH 4-Cyl. 154 Diesel</b>		
1967-1964		
Belt - Fan; W/35 1/2" Belt O.C. ....	709502R1	TR22350
Belt - Fan; W/37 3/4" Belt O.C. ....	237153R1	TR22373
Belt - Gen. ....	48878D	▲9313HD
<b>444</b>		
<b>IH 4-Cyl. 152</b>		
1971-1967		
Belt - Fan & Alt.; W/43 1/8" Belt O.C. ....	387920R1	7425
Belt - Fan & Alt./Gen.; W/43 5/8" Belt O.C. ..	403580R1	7430
Hose - Lower - Eng. To Pipe .....		24222
Hose - Lower - Pipe To Rad. ....		24232
Hose - By Pass .....		28439
<b>IH 4-Cyl. 154 Diesel</b>		
1971-1967		
Belt - Alt. ....	401691R1	▲9341HD
Belt - Fan .....	237153R1	TR22373
Hose - Upper .....		☞20065
Hose - Lower .....		☞20661
		or ●25251
<b>450</b>		
<b>IH 4-Cyl. 281</b>		
1958-1956		
Belt - Fan .....	16131DA	TR28454
Belt - Gen. ....	49341D	▲9335HD
Belt - P.S. ....	363197R2	TR24500
<b>IH 4-Cyl. 281 Diesel</b>		
1958-1956		
Belt - Fan .....	69490DA	TR30467
Belt - Gen. ....	52318DA	9279
<b>450 Farmall</b>		
<b>IH 4-Cyl. 281</b>		
1958-1956		
Belt - Fan .....	16131DA	TR28454
Belt - Gen. ....	49341D	▲9335HD
Belt - P.S. ....	363197R2	TR30506
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
Hose - By Pass .....		24224
<b>IH 4-Cyl. 281 Diesel</b>		
1958-1956		
Belt - Fan .....	16131DA	TR28454
Belt - Gen. ....	49341D	▲9335HD
Belt - P.S. ....	363197R2	TR30506
Hose - Upper .....		24234
Hose - By Pass .....		24224
<b>IH 4-Cyl. 281 LPG</b>		
1958-1956		
Belt - Fan .....	16131DA	TR28454
Belt - Gen. ....	49341D	▲9335HD
Belt - P.S. ....	363197R2	TR30506
<b>454</b>		
<b>IH 3-Cyl. 179 Diesel</b>		
1973-1971		
Belt - Fan & Alt. ....	534310R1	▲9630HD
Hose - Upper .....		●26503
<b>IH 4-Cyl. 157</b>		
1973-1971		
Belt - Fan & Alt. ....	523030R2	7530
Hose - Upper .....		☞21660
		or ●25474

☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>460</b>		
<b>IH 6-Cyl. 221</b>		
1963-1958		
Belt - Fan & Alt. ....	403617R1	▲9470HD
Belt - Fan & Gen. ....	149635R1	▲9463HD
Hose - Upper .....		≈<20611
Hose - Lower .....		●26509
Hose - By Pass .....		28441
<b>IH 6-Cyl. 236 Diesel</b>		
1963-1958		
Belt - Fan .....	369290R1	▲9463HD
Belt - Fan & Gen. ....	385738R1	▲9490HD
Belt - Gen. ....	316250R1	▲9490HD
Belt - W.P. & Gen. ....		▲9463HD
Hose - Upper .....		≈<20611
Hose - Lower .....		24232
Hose - By Pass .....		28441
<b>460 Farmall</b>		
<b>IH 6-Cyl. 221</b>		
1963-1958		
Belt - Fan & Alt. ....	403617R1	▲9470HD
Belt - Fan & Gen. ....	149635R1	▲9463HD
Hose - Upper .....		●26510
Hose - Lower .....		●26509
Hose - By Pass .....		28441
<b>IH 6-Cyl. 236 Diesel</b>		
1963-1958		
Belt - Fan .....	369290R1	▲9463HD
Belt - Fan & Gen. ....	385738R1	▲9490HD
Belt - Gen. ....	316250R1	▲9490HD
Belt - W.P. & Gen. ....		▲9463HD
Hose - Upper .....		●26510
Hose - Lower .....		24232
Hose - By Pass .....		28441
<b>464</b>		
<b>IH 4-Cyl. 175</b>		
1978-1973		
Belt - Fan & Alt. ....	1532030R2	▲9525HD
Hose - Lower .....		≈<21660
		or ●25474
<b>484</b>		
<b>IH 3-Cyl. 179 Diesel</b>		
1984-1978		
Belt - Fan & Alt. ....		▲9625HD
Hose - Upper .....		●26503
Hose - Lower .....		●25530
<b>500</b>		
<b>IH 4-Cyl. 146</b>		
1969-1965		
Belt - Fan & Gen. ....	676645R1	7425
<b>500C</b>		
<b>IH D155 Diesel</b>		
1974-1969		
Belt - Fan; W/21/32" Belt T.W.; W/36 3/4"		
Belt O.C. ....	676620R1	TR22363
Belt - Fan; W/3/8" Belt T.W.; W/37 1/8"		
Belt O.C. ....	676622R1	7370
Belt - Gen. ....	676626R1	7312
<b>504; 504 Farmall</b>		
<b>IH 4-Cyl. 152</b>		
1968-1960		
Hose - Upper .....		≈<20206
		or ●26509
Hose - Lower - Eng. To Pipe .....		24222
Hose - Lower - Pipe To Rad. ....		24240
Hose - By Pass .....		28439

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>504; 504 Farmall - Continued</b>		
<b>IH 4-Cyl. 188 Diesel</b>		
1968-1960		
Hose - Upper .....		≈<20206
		or ●26509
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24240
Hose - By Pass .....		20338
<b>544; 544 Farmall</b>		
<b>IH 4-Cyl. 200</b>		
1973-1968		
Belt - Fan & Alt. ....	403303R1	7545
Belt - Fan & Gen. ....	314606C2	7541
Hose - Lower .....		●25527
<b>IH 4-Cyl. 239 Diesel</b>		
1973-1968		
Belt - Fan .....	534311R1	▲9610HD
Belt - Fan & Alt. ....	401128R1	▲9580HD
Belt - W.P. & Alt. ....	315969R1	▲9490HD
<b>560</b>		
<b>IH 6-Cyl. 263</b>		
1963-1958		
Belt - Fan .....	369290R1	▲9463HD
Belt - W.P. & Gen. ....	369290R1	▲9463HD
Hose - Upper .....		●26510
Hose - Lower .....		●26509
Hose - By Pass .....		≈<20338
<b>IH 6-Cyl. 282 Diesel</b>		
1963-1958		
Belt - Fan .....	369290R1	▲9463HD
Belt - W.P. & Gen. ....	190502R1	▲9490HD
Hose - Upper .....		●26522
Hose - Lower .....		24232
Hose - By Pass .....		28441
<b>560 Farmall</b>		
<b>IH 6-Cyl. 263</b>		
1963-1958		
Hose - Upper .....		●26510
Hose - Lower .....		●26509
Hose - By Pass .....		≈<20338
<b>IH 6-Cyl. 282 Diesel</b>		
1963-1958		
Belt - Fan .....	403348R1	▲9463HD
Belt - W.P. & Gen. ....	316250R1	▲9490HD
Hose - Upper .....		●26522
Hose - Lower .....		24232
Hose - By Pass .....		28441
<b>574</b>		
<b>IH 4-Cyl. 200</b>		
1978-1970		
Belt - Fan & Alt./Gen. ....	532031R2	7525
Hose - Lower .....		≈<21794
		or ●25476
<b>IH 4-Cyl. 239 Diesel</b>		
1978-1970		
Belt - Fan & Alt./Gen. ....	534311R1	▲9610HD
Belt - W.P. & Alt. ....	403303R1	7545
Hose - Upper .....		≈<20957
<b>584</b>		
<b>IH 4-Cyl. 206 Diesel</b>		
1984-1978		
Belt - Fan & Alt. ....		▲9605HD
Hose - Upper .....		≈<21794
		or ●25476
Hose - Lower .....		●25528
Hose - By Pass .....		24232

≈<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>600</b>		
<b>IH 4-Cyl. 350</b>		
1957-1956		
Belt - Fan; W/O P.S.; W/O Hydra-Touch		
Hydraulics	48042DB	TR30484
Belt - Fan; W/P.S.; W/O Hydra-Touch		
Hydraulics	363599R1	TR28557
Belt - Gen.	365686R1	▲9380HD
Hose - Upper		24234
Hose - Lower		24234
Hose - By Pass		24224
<b>IH 4-Cyl. 350 Diesel</b>		
1957-1956		
Belt - Fan; W/O P.S.; W/O Hydra-Touch		
Hydraulics	48042DB	TR30484
Belt - Fan; W/P.S.; W/O Hydra-Touch		
Hydraulics	363599R1	TR28557
Belt - Gen.	48878D	▲9313HD
Hose - Upper		24234
Hose - Lower		24234
Hose - By Pass		24224
<b>606</b>		
<b>IH 6-Cyl. 221</b>		
1967-1962		
Belt - Fan & Alt.	403617R1	▲9470HD
Belt - Fan & Gen.	149635R1	▲9463HD
Hose - Upper		✕20611
Hose - Lower		●26509
Hose - By Pass		20338
<b>IH 6-Cyl. 236 Diesel</b>		
1967-1962		
Belt - Fan & Gen.; Ser. No. 13949 & Before	316250R1	▲9490HD
Belt - Fan & Gen.; Ser. No. 13950 & After	382228R1	▲9520HD
Hose - Upper		✕20611
Hose - Lower		24232
Hose - By Pass		28441
<b>650</b>		
<b>IH 4-Cyl. 350</b>		
1958-1956		
Belt - Fan; W/O P.S.; W/O Hydra-Touch		
Hydraulics	48042DB	TR30484
Belt - Fan; W/P.S.; W/O Hydra-Touch		
Hydraulics	363599R1	TR28557
Belt - Gen.	365686R1	▲9380HD
Hose - Upper		24234
Hose - Lower		24234
Hose - By Pass		24224
<b>IH 4-Cyl. 350 Diesel</b>		
1958-1956		
Belt - Fan; W/O P.S.; W/O Hydra-Touch		
Hydraulics	48042DB	TR30484
Belt - Fan; W/P.S.; W/O Hydra-Touch		
Hydraulics	363599R1	TR28557
Belt - Gen.	48878D	▲9313HD
Hose - Upper		24234
Hose - Lower		24234
Hose - By Pass		24224
<b>656</b>		
<b>IH 6-Cyl. 263</b>		
1973-1966		
Belt - Fan	396829R1	▲9440HD
Belt - W.P. & Alt.	403617R1	▲9470HD
Hose - Upper		●26510
Hose - Lower		●26509
Hose - By Pass		20338
<b>IH 6-Cyl. 281 Diesel</b>		
1973-1966		
Belt - A.C.	395463R1	▲9620HD
Belt - Fan; W/44" Belt O.C.	396829R1	▲9440HD
Belt - Fan; W/48 1/4" Belt O.C.	378113R2	▲9480HD
Belt - Fan; W/49 1/4" Belt O.C.	385738R1	▲9490HD
Belt - Fan; W/51 1/4" Belt O.C.	396830R1	▲9510HD
Belt - W.P. & Alt./Gen.		▲9490HD
Hose - Upper		●26510
Hose - Lower		●26507
Hose - By Pass		28441

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>656 - Continued</b>		
<b>IH 6-Cyl. 281 Diesel - Continued</b>		
1973-1966 - Continued		
Belt - Fan; W/49 1/4" Belt O.C.	385738R1	▲9490HD
Belt - Fan; W/51 1/4" Belt O.C.	396830R1	▲9510HD
Belt - W.P. & Alt./Gen.		▲9490HD
Hose - Upper		●26510
Hose - Lower		●26507
Hose - By Pass		28441
<b>656 Farmall</b>		
<b>IH 6-Cyl. 263</b>		
1972-1965		
Belt - A.C.	395463R1	▲9620HD
Belt - Fan	393415R1	▲9470HD
Belt - W.P. & Alt./Gen.; Ser. No. 23107 & Before	332562R1	▲9463HD
Hose - Upper		●26510
Hose - Lower		●26509
Hose - By Pass		20338
<b>IH 6-Cyl. 281 Diesel</b>		
1972-1965		
Belt - A.C.	395463R1	▲9620HD
Belt - Fan	403617R1	▲9470HD
Belt - W.P. & Alt./Gen.		▲9490HD
Hose - Upper		●26510
Hose - Lower		●26507
Hose - By Pass		28441
<b>656 Hydro Farmall</b>		
<b>IH 6-Cyl. 263</b>		
1973-1968		
Belt - A.C.	395463R1	▲9620HD
Belt - Fan	393415R1	▲9470HD
Belt - W.P. & Alt./Gen.; Ser. No. 23107 & Before	332562R1	▲9463HD
Hose - Upper		●26510
Hose - Lower		●26509
Hose - By Pass		20338
<b>IH 6-Cyl. 281 Diesel</b>		
1973-1968		
Belt - A.C.	395463R1	▲9620HD
Belt - Fan	403617R1	▲9470HD
Belt - W.P. & Alt./Gen.		▲9490HD
Hose - Upper		●26510
Hose - Lower		●26507
Hose - By Pass		28441
<b>656H</b>		
<b>IH 6-Cyl. 263</b>		
1973-1967		
Belt - Fan	403348R1	▲9463HD
Belt - W.P. & Alt.	403617R1	▲9470HD
Hose - Upper		●26510
Hose - Lower		●26509
Hose - By Pass		20338
<b>IH 6-Cyl. 281 Diesel</b>		
1973-1967		
Belt - A.C.	395463R1	▲9620HD
Belt - Fan; W/44" Belt O.C.	396829R1	▲9440HD
Belt - Fan; W/48 1/4" Belt O.C.	378113R2	▲9480HD
Belt - Fan; W/49 1/4" Belt O.C.	385738R1	▲9490HD
Belt - Fan; W/51 1/4" Belt O.C.	396830R1	▲9510HD
Belt - W.P. & Alt./Gen.		▲9490HD
Hose - Upper		●26510
Hose - Lower		●26507
Hose - By Pass		28441
<b>660 Tractor</b>		
<b>IH 6-Cyl. 263</b>		
1963-1959		
Belt - Fan	372596R1	▲9480HD
Belt - W.P. & Gen.	369290R1	▲9463HD
Hose - Lower		●26509

✕Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>660 Tractor – Continued</b>		
<b>IH 6-Cyl. 263 – Continued</b>		
1963-1959 – Continued		
Hose - By Pass .....		20338
<b>IH 6-Cyl. 281 Diesel</b>		
1963-1959		
Belt - Fan .....	372596R1	▲9480HD
Belt - W.P. & Gen. ....	190502R1	▲9490HD
Hose - Lower .....		●26507
<b>664</b>		
<b>IH 4-Cyl. 239 Diesel</b>		
1974-1972		
Belt - Fan & Alt./Gen. ....	401128R2	▲9580HD
Hose - Lower .....		●26511
<b>666; 666 Farmall</b>		
<b>IH 6-Cyl. 291</b>		
1976-1972		
Belt - Fan; Ser. No. 11050 & Before .....	403617R1	▲9470HD
Belt - Fan; Ser. No. 11051 & After .....	406097R1	▲9570HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C. ....	393415R1	▲9470HD
Belt - W.P. & Alt.; W/64 1/4" Belt O.C. ....	530186R1	▲9640HD
Hose - Lower .....		●26510
Hose - By Pass .....		20338
<b>IH 6-Cyl. 312 Diesel</b>		
1976-1972		
Belt - Fan .....	393415R1	▲9470HD
Belt - W.P. & Alt. ....	65999C1	TR24638
Hose - Upper .....		●26516
Hose - By Pass .....		24220
<b>674</b>		
<b>IH 4-Cyl. 238 Diesel</b>		
1978-1973		
Belt - Fan & Alt.; W/Syncro Mesh Trans. ....	403303R1	7545
<b>684</b>		
<b>IH 4-Cyl. 239 Diesel</b>		
1984-1978		
Belt - Fan & Alt. ....	527470R1	▲9605HD
<b>686</b>		
<b>IH 6-Cyl. 291</b>		
1981-1976		
Belt - Fan .....	403617R1	▲9470HD
Belt - W.P. & Alt. ....	530186R1	▲9640HD
Hose - Lower .....		●26510
Hose - By Pass .....		20338
<b>IH 6-Cyl. 312 Diesel</b>		
1981-1976		
Belt - Fan .....	403617R1	▲9470HD
Belt - W.P. & Alt. ....	65999R1	TR24638
Hose - Upper .....		●26516
Hose - By Pass .....		24220
<b>706</b>		
<b>IH 6-Cyl. 263</b>		
1965-1963		
Belt - Fan; W/47 1/4" Belt O.C. ....	393415R1	▲9470HD
Belt - Fan; W/48 1/4" Belt O.C. ....	378113R1	▲9480HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C. ....	393415R1	▲9470HD
Belt - W.P. & Alt./Gen.; W/46 1/2" Belt O.C. ....		▲9463HD
Belt - W.P. & Gen. ....	316250R1	▲9490HD
Hose - Upper; Ser. No. 37236 & Before .....		●26510
Hose - Lower; Ser. No. 5273 & Before .....		●26509
Hose - Lower; Ser. No. 5274 & After .....		●26510
Hose - By Pass .....		20338
<b>IH 6-Cyl. 282 Diesel</b>		
1965-1963		
Belt - A.C.; W/62 1/4" Belt O.C. ....	395463R1	▲9620HD

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>706 – Continued</b>		
<b>IH 6-Cyl. 282 Diesel – Continued</b>		
1965-1963 – Continued		
Belt - A.C.; W/72 1/4" Belt O.C. ....	397397R1	▲9720HD
Belt - Fan; Ser. No. 49663 & Before .....	378113R1	▲9480HD
Belt - Fan; Ser. No. 49664 & After .....	385674R1	▲9490HD
Belt - W.P. & Alt.; W/64 1/4" Belt O.C. ....	396543R1	▲9640HD
Belt - W.P. & Alt./Gen.; W/49 1/4" Belt O.C. ....		▲9490HD
Hose - Upper; Ser. No. 5273 & Before .....		●26510
Hose - Upper; Ser. No. 5274 & After .....		≈<20611
		or ●26508
Hose - Lower; Ser. No. 5273 & Before .....		24232
		or ●26507
Hose - Lower; Ser. No. 5274 & After .....		●26524
Hose - By Pass .....		28441
<b>IH 6-Cyl. 291</b>		
1967-1966		
Belt - Fan; W/47 1/4" Belt O.C. ....	393415R1	▲9470HD
Belt - Fan; W/48 1/4" Belt O.C. ....	378113R1	▲9480HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C. ....	393415R1	▲9470HD
Belt - W.P. & Alt./Gen.; W/46 1/2" Belt O.C. ....		▲9463HD
Belt - W.P. & Gen. ....	316250R1	▲9490HD
Hose - Upper; Ser. No. 37236 & Before .....		●26510
Hose - Lower; Ser. No. 5273 & Before .....		●26509
Hose - Lower; Ser. No. 5274 & After .....		●26510
Hose - By Pass .....		20338
<b>IH 6-Cyl. 310 Diesel</b>		
1967-1966		
Belt - A.C.; W/62 1/4" Belt O.C. ....	395463R1	▲9620HD
Belt - A.C.; W/72 1/4" Belt O.C. ....	397397R1	▲9720HD
Belt - Fan; Ser. No. 49663 & Before .....	378113R1	▲9480HD
Belt - Fan; Ser. No. 49664 & After .....	385674R1	▲9490HD
Belt - W.P. & Alt.; W/64 1/4" Belt O.C. ....	396543R1	▲9640HD
Belt - W.P. & Alt./Gen.; W/49 1/4" Belt O.C. ....		▲9490HD
Hose - Upper; Ser. No. 5273 & Before .....		●26510
Hose - Upper; Ser. No. 5274 & After .....		≈<20611
		or ●26508
Hose - Lower; Ser. No. 5273 & Before .....		24232
		or ●26507
Hose - Lower; Ser. No. 5274 & After .....		●26524
Hose - By Pass .....		28441
<b>706 Farmall</b>		
<b>IH 6-Cyl. 263</b>		
1967-1963		
Belt - Fan; W/47 1/4" Belt O.C. ....	393415R1	▲9470HD
Belt - Fan; W/48 1/4" Belt O.C. ....	378113R1	▲9480HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C. ....	393415R1	▲9470HD
Belt - W.P. & Alt./Gen.; W/46 1/2" Belt O.C. ....		▲9463HD
Belt - W.P. & Gen. ....	316250R1	▲9490HD
Hose - Upper; Ser. No. 37236 & Before .....		●26510
Hose - Lower; Ser. No. 37236 & Before .....		●26509
Hose - Lower; Ser. No. 37237 & After .....		●26510
Hose - By Pass .....		20338
<b>IH 6-Cyl. 263 LPG</b>		
1967-1963		
Hose - Upper; Ser. No. 37236 & Before .....		●26510
Hose - Lower; Ser. No. 37236 & Before .....		●26509
Hose - Lower; Ser. No. 37237 & After .....		●26510
Hose - By Pass .....		20338
<b>IH 6-Cyl. 282 Diesel</b>		
1967-1963		
Belt - A.C.; W/62 1/4" Belt O.C. ....	395463R1	▲9620HD
Belt - A.C.; W/72 1/4" Belt O.C. ....	397397R1	▲9720HD
Belt - Fan; Ser. No. 49663 & Before .....	378113R1	▲9480HD
Belt - Fan; Ser. No. 49664 & After .....	385674R1	▲9490HD
Belt - W.P. & Alt.; W/64 1/4" Belt O.C. ....	396543R1	▲9640HD
Belt - W.P. & Alt./Gen.; W/49 1/4" Belt O.C. ....		▲9490HD
Hose - Upper; Ser. No. 37236 & Before .....		●26510
Hose - Upper; Ser. No. 37237 & After .....		≈<20611
		or ●26508
Hose - Lower; Ser. No. 37237 & After .....		●26524
Hose - By Pass .....		28441

≈<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>706 Farmall - Continued</b>		
<b>IH 6-Cyl. 291</b>		
1967-1963		
Hose - Upper; Ser. No. 37236 & Before		●26510
Hose - Lower; Ser. No. 37236 & Before		●26509
Hose - Lower; Ser. No. 37237 & After		●26510
Hose - By Pass		20338
<b>IH 6-Cyl. 291 LPG</b>		
1967-1963		
Hose - Upper; Ser. No. 37236 & Before		●26510
Hose - Lower; Ser. No. 37236 & Before		●26509
Hose - Lower; Ser. No. 37237 & After		●26510
Hose - By Pass		20338
<b>IH 6-Cyl. 310 Diesel</b>		
1967-1963		
Hose - Upper; Ser. No. 37236 & Before		●26510
Hose - Upper; Ser. No. 37237 & After		⊗20611
		or ●26508
Hose - Lower; Ser. No. 37237 & After		●26524
Hose - By Pass		24224
<b>756; 756 Farmall</b>		
<b>IH 6-Cyl. 291</b>		
1971-1967		
Belt - Fan; W/47 1/4" Belt O.C.	393415R1	▲9470HD
Belt - Fan; W/48 1/4" Belt O.C.	378113R1	▲9480HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C.	393415R1	▲9470HD
Belt - W.P. & Alt./Gen.; W/46 1/2" Belt O.C.		▲9463HD
Belt - W.P. & Gen.	316250R1	▲9490HD
Hose - Lower		●26510
<b>IH 6-Cyl. 310 Diesel</b>		
1971-1967		
Belt - A.C.	395463R1	▲9620HD
Belt - Fan	396543R1	▲9640HD
Belt - W.P. & Alt.; W/64 1/4" Belt O.C.	396543R1	▲9640HD
Belt - W.P. & Alt./Gen.; W/49 1/4" Belt O.C.		▲9490HD
Hose - Upper		⊗20611
		or ●26508
Hose - Lower		●26524
Hose - By Pass		24224
<b>766; 766 Farmall</b>		
<b>IH 6-Cyl. 291</b>		
1976-1971		
Belt - A.C.	242270R2	▲9380HD
Belt - Fan	403617R1	▲9470HD
Belt - W.P. & Alt.	403617R1	▲9470HD
<b>IH 6-Cyl. 360 Diesel</b>		
1976-1971		
Belt - A.C.	242270R2	▲9380HD
Belt - W.P. & Alt.	532746R1	②TR22648
Hose - Upper		●26516
Hose - Lower		24240
<b>784</b>		
<b>IH 4-Cyl. 246 Diesel</b>		
1984-1978		
Belt - Fan & Alt.		▲9610HD
<b>806</b>		
<b>IH 6-Cyl. 301</b>		
1967-1963		
Belt - A.C.	395463R1	▲9620HD
Belt - Fan; W/47 1/4" Belt O.C.	393415R1	▲9470HD
Belt - Fan; W/48 1/4" Belt O.C.	378113R1	▲9480HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C.	393415R1	▲9470HD
Belt - W.P. & Alt./Gen.; W/46 1/2" Belt O.C.		▲9463HD
Hose - Lower		●26510
Hose - By Pass		20338

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>806 - Continued</b>		
<b>IH 6-Cyl. 361 Diesel</b>		
1967-1963		
Belt - A.C.		9765
Belt - Fan & Alt.	385120R1	TR22664
Belt - Fan & Gen.	380060R1	TR22657
Hose - Upper		●26511
Hose - Lower		24224
		or ●26515
Hose - By Pass		24224
<b>806 Farmall</b>		
<b>IH 6-Cyl. 301</b>		
1967-1963		
Belt - A.C.	395463R1	▲9620HD
Belt - Fan; W/47 1/4" Belt O.C.	393415R1	▲9470HD
Belt - Fan; W/48 1/4" Belt O.C.	378113R1	▲9480HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C.	393415R1	▲9470HD
Belt - W.P. & Alt./Gen.; W/46 1/2" Belt O.C.		▲9463HD
Hose - Lower		●26510
Hose - By Pass		20338
<b>IH 6-Cyl. 301 LPG</b>		
1967-1963		
Belt - A.C.	395463R1	▲9620HD
Belt - Fan; W/47 1/4" Belt O.C.	393415R1	▲9470HD
Belt - Fan; W/48 1/4" Belt O.C.	378113R1	▲9480HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C.	393415R1	▲9470HD
Belt - W.P. & Alt./Gen.; W/46 1/2" Belt O.C.		▲9463HD
<b>IH 6-Cyl. 361 Diesel</b>		
1967-1963		
Belt - A.C.		9765
Belt - Fan & Alt.	385120R1	TR22664
Belt - Fan & Gen.	380060R1	TR22657
Hose - Upper		●26511
Hose - Lower		24224
		or ●26515
Hose - By Pass		24224
<b>826</b>		
<b>IH 6-Cyl. 301</b>		
1971-1969		
Belt - Fan & Alt.	403617R1	▲9470HD
Belt - W.P. & Alt.	403617R1	▲9470HD
Hose - Upper		●26509
Hose - Lower		●26524
<b>IH 6-Cyl. 358 Diesel</b>		
1971-1969		
Belt - Fan & Alt.	530076R1	▲9640HD
Hose - Upper		●26509
Hose - Lower		●26524
<b>826 Farmall</b>		
<b>IH 6-Cyl. 358 Diesel</b>		
1971-1969		
Belt - Fan & Alt.	530076R1	▲9640HD
Hose - Upper		●26509
Hose - Lower		●26524
<b>826H; 826H Farmall</b>		
<b>IH 6-Cyl. 301</b>		
1971-1969		
Belt - Fan & Alt.	403617R1	▲9470HD
Belt - W.P. & Alt.	403617R1	▲9470HD
Hose - Upper		●26509
Hose - Lower		●26524
<b>IH 6-Cyl. 358 Diesel</b>		
1971-1969		
Belt - Fan & Alt.	530076R1	▲9640HD
Hose - Upper		●26509
Hose - Lower		●26524

②Two Required ⊗Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>856; 856 Farmall</b>		
<b>IH 6-Cyl. 301</b>		
1971-1967		
Belt - A.C. ....	395463R1	▲9620HD
Belt - Fan ....	403617R1	▲9470HD
Belt - W.P. & Alt. ....	403617R1	▲9470HD
Hose - Lower ....		●26510
Hose - By Pass ....		20338
<b>IH 6-Cyl. 407 Diesel</b>		
1971-1967		
Belt - A.C. ....	395462R1	9765
Belt - Fan & Alt. ....	385120R2	TR22664
Hose - Upper ....		●26511
Hose - Lower ....		●26516
Hose - By Pass ....		≈<20573
<b>884</b>		
<b>IH 4-Cyl. 268 Diesel</b>		
1984-1978		
Belt - Fan & Alt. ....		▲9610HD
<b>886</b>		
<b>IH 6-Cyl. 360 Diesel</b>		
1981-1976		
Hose - Upper ....		●26516
Hose - Lower ....		24236
<b>966; 966 Farmall</b>		
<b>IH 6-Cyl. 414 Diesel</b>		
1976-1971		
Belt - A.C. ....	242270R2	▲9380HD
Belt - Fan & Alt.; W/Dual Belts ....	537072R1	②TR22648
Belt - Fan & Alt.; W/Single Belt ....	532746R1	TR22648
Belt - Fan & W.P. ....	532746R1	②TR22648
Hose - Upper ....		●26516
Hose - Lower ....		24236
<b>986</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1981-1976		
Belt - Fan & Alt.; W/A.C. ....	532746R1	②TR22648
Belt - Fan & Alt.; W/O A.C. ....	532746R1	TR22648
Belt - Fan To A.C. ....	874097C1	▲9395HD
Hose - Upper ....		●26516
Hose - Lower ....		24236
Hose - By Pass ....		24220
<b>1026 Hydro; 1026 Hydro Farmall</b>		
<b>IH 6-Cyl. 407 Diesel</b>		
1971-1969		
Belt - A.C. ....		▲9610HD
Belt - Fan & Alt. ....	385120R2	TR22664
<b>1066; 1066 Farmall</b>		
<b>IH 6-Cyl. 414 Diesel</b>		
1976-1971		
Belt - A.C.; W/38 1/4" Belt O.C. ....	242270R2	▲9380HD
Belt - A.C.; W/39 3/4" Belt O.C. ....	874097C1	▲9395HD
Belt - Fan & Alt.; W/1/2" Belt T.W.; W/62 3/4" Belt O.C. ....	480240C91	②▲9625HD
Belt - Fan & Alt.; W/Dual Belts; W/21/32" Belt T.W.; W/65" Belt O.C. ....	532746R1	②TR22648
Belt - Fan & Alt.; W/Single Belt; W/21/32" Belt T.W.; W/65" Belt O.C. ....	532746R1	TR22648
Belt - W.P. & Alt. ....	532746R1	TR22648
Hose - Lower ....		24236
<b>1086</b>		
<b>IH 6-Cyl. 414 Diesel</b>		
1981-1976		
Belt - A.C. ....	874097C1	▲9395HD
Belt - Fan & Alt.; W/A.C. ....	532746R1	②TR22648
Belt - Fan & Alt.; W/O A.C. ....	532746R1	TR22648

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>1206; 1206 Farmall</b>		
<b>IH 6-Cyl. 361 Diesel</b>		
1967		
Belt - A.C. ....		9765
Belt - Fan & Alt. ....		TR24664
Hose - Lower ....		●26515
Hose - By Pass ....		≈<20267
<b>1966-1965</b>		
Belt - A.C. ....		9765
Belt - Fan & Alt. ....		TR22664
Hose - Lower ....		●26515
Hose - By Pass ....		≈<20267
<b>1256; 1256 Farmall</b>		
<b>IH 6-Cyl. 407 Diesel</b>		
1969-1967		
Belt - A.C. ....		▲9610HD
Belt - Fan & Alt. ....	385120R2	TR22664
Hose - Upper ....		●26511
Hose - Lower ....		●26516
Hose - By Pass ....		≈<20573
<b>1456; 1456 Farmall</b>		
<b>IH 6-Cyl. 407 Diesel</b>		
1971-1969		
Belt - A.C. ....		▲9610HD
Belt - Fan & Alt. ....	385120R2	TR22664
Hose - Upper ....		●26511
Hose - Lower ....		●26516
Hose - By Pass ....		≈<20573
<b>1466; 1466 Farmall</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1976-1971		
Belt - A.C.; W/38 1/4" Belt O.C. ....	242270R2	▲9380HD
Belt - A.C.; W/39 3/4" Belt O.C. ....	874097C1	▲9395HD
Belt - Fan & Alt.; W/1/2" Belt T.W.; W/62 3/4" Belt O.C. ....	480240C91	②▲9625HD
Belt - Fan & Alt.; W/Dual Belts; W/21/32" Belt T.W.; W/65" Belt O.C. ....	532746R1	②TR22648
Belt - Fan & Alt.; W/Single Belt; W/21/32" Belt T.W.; W/65" Belt O.C. ....	532746R1	TR22648
Belt - W.P. & Alt. ....	532746R1	TR22648
Hose - Upper ....		●26523
<b>1468; 1468 Farmall</b>		
<b>IH V-8 550 Diesel</b>		
1974-1971		
Belt - A.C. ....	527621R1	7480
Belt - Fan; W/50 3/8" Belt O.C. ....	427205C91	②▲9500HD
Belt - Fan; W/51 3/8" Belt O.C. ....		▲9510HD
Belt - W.P. & Alt. ....	236161R2	7470
Hose - Lower - Eng. To Pipe ....		≈<20530
<b>1486</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1981-1976		
Belt - Fan & Alt.; W/A.C. ....	532746R1	②TR22648
Belt - Fan & Alt.; W/O A.C. ....	532746R1	TR22648
Belt - Fan To A.C. ....	874097C1	▲9395HD
Hose - Upper ....		●26516
<b>1566</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1976-1973		
Belt - A.C. ....	65337C2	▲9375HD
Belt - Fan & Alt. ....	532746R1	②TR22648
Hose - Upper ....		●26523
<b>1568</b>		
<b>IH V-8 550 Diesel</b>		
1976-1973		
Belt - Alt. ....	236161R2	7470
Belt - Fan ....	242268R1	②▲9500HD

②Two Required ≈<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Agricultural Equipment





Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>1568 – Continued</b>		
<b>IH V-8 550 Diesel – Continued</b>		
1976-1973 – Continued		
Hose - Lower - Eng. To Pipe .....		≅20530
<b>1586</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1981-1976		
Belt - Fan & Alt.; W/A.C. ....	532746R1	②TR22648
Belt - Fan & Alt.; W/O A.C. ....	532746R1	TR22648
Belt - Fan To A.C. ....	874097C1	♣9395HD
Hose - Upper .....		●26516
<b>2400A; 2400A Lo-Boy</b>		
<b>IH 4-Cyl. 157</b>		
1974-1970		
Belt - Fan & Alt. ....	523030R2	7530
Hose - Upper .....		≅21660
		or ●25474
<b>IH 4-Cyl. 179 Diesel</b>		
1974-1970		
Belt - Fan & Alt. ....	534310R1	♣9630HD
Hose - Upper .....		●26503
<b>2400B; 2400B Lo-Boy</b>		
<b>IH 4-Cyl. 157</b>		
1977-1974		
Hose - Lower .....		≅21660
		or ●25474
<b>IH 4-Cyl. 179 Diesel</b>		
1977-1974		
Hose - Lower .....		≅21660
		or ●25474
<b>2404 Industrial</b>		
<b>IH 4-Cyl. 135</b>		
1967-1960		
Belt - Fan & Gen. ....	403580R1	7430
Hose - Lower; W/1 3/8" I.D. Hose .....		24222
Hose - Lower; W/2" I.D. Hose .....		24232
Hose - By Pass .....		28439
<b>2424 Industrial; 2424 Lo-Boy Industrial</b>		
<b>IH 4-Cyl. 146</b>		
1968-1964		
Belt - Fan & Gen. ....	403580R1	7430
<b>IH 4-Cyl. 154 Diesel</b>		
1968-1964		
Belt - Fan .....	709502R1	TR22350
<b>2444 Industrial; 2444 Lo-Boy Industrial</b>		
<b>IH 4-Cyl. 152</b>		
1971-1967		
Belt - Fan & Alt.; W/43 1/8" Belt O.C. ....	387920R1	7425
Belt - Fan & Alt./Gen.; W/43 5/8" Belt O.C. ..	403580R1	7430
Hose - Lower - Eng. To Pipe .....		24222
Hose - Lower - Pipe To Rad. ....		24232
Hose - By Pass .....		28439
<b>IH 4-Cyl. 154 Diesel</b>		
1971-1967		
Belt - Alt. ....	401691R1	♣9341HD
Belt - Fan .....	237153R1	TR22373
Hose - Upper .....		≅20065
Hose - Lower .....		≅20661
		or ●25251
<b>2500A</b>		
<b>IH 4-Cyl. 200</b>		
1974-1970		
Belt - Fan & Alt./Gen. ....	532031R2	7525

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>2500A – Continued</b>		
<b>IH 4-Cyl. 200 – Continued</b>		
1974-1970 – Continued		
Hose - Lower .....		≅21794
		or ●25480
<b>IH 4-Cyl. 239 Diesel</b>		
1974-1970		
Belt - Fan & Alt./Gen. ....	534311R1	♣9610HD
Belt - W.P. & Alt. ....	403303R1	7545
Hose - Upper .....		≅20957
<b>2500A Lo-Boy</b>		
<b>IH 4-Cyl. 200</b>		
1974-1970		
Belt - Fan & Alt./Gen. ....	532031R2	7525
<b>IH 4-Cyl. 239 Diesel</b>		
1974-1970		
Belt - Fan & Alt./Gen. ....	534311R1	♣9610HD
Belt - W.P. & Alt. ....	403303R1	7545
<b>2500B</b>		
<b>IH 4-Cyl. 200</b>		
1977-1974		
Belt - Fan & Alt. ....	532030R2	7520
Hose - Lower .....		≅21794
		or ●25476
<b>IH 4-Cyl. 239 Diesel</b>		
1977-1974		
Belt - Fan & Alt./Gen. ....	534311R1	♣9610HD
Belt - W.P. & Alt. ....	403303R1	7545
Hose - Upper .....		≅20957
		or ●26501
<b>2500B Lo-Boy</b>		
<b>IH 4-Cyl. 200</b>		
1977-1974		
Belt - Fan & Alt. ....	532030R2	7520
<b>IH 4-Cyl. 239 Diesel</b>		
1977-1974		
Belt - Fan & Alt./Gen. ....	534311R1	♣9610HD
Belt - W.P. & Alt. ....	403303R1	7545
Hose - Upper .....		≅20957
		or ●26501
<b>2504 Industrial</b>		
<b>IH 4-Cyl. 152</b>		
1968-1960		
Hose - Upper .....		≅20206
		or ●26509
Hose - Lower - Eng. To Pipe .....		24222
Hose - Lower - Pipe To Rad. ....		24240
Hose - By Pass .....		28439
<b>IH 4-Cyl. 188 Diesel</b>		
1968-1960		
Hose - Upper .....		≅20206
		or ●26509
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24240
Hose - By Pass .....		20338
<b>2544 Industrial</b>		
<b>IH 4-Cyl. 200</b>		
1973-1968		
Belt - Fan & Alt. ....	403303R1	7545
Belt - Fan & Gen. ....	314606C2	7541
Hose - Lower .....		●25527
<b>IH 4-Cyl. 239 Diesel</b>		
1973-1968		
Belt - Fan .....	534311R1	♣9610HD
Belt - Fan & Alt. ....	401128R1	♣9580HD
Belt - W.P. & Alt. ....	315969R1	♣9490HD

②Two Required ≅Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>2606 Industrial</b>		
<b>IH 6-Cyl. 236 Diesel</b>		
1967-1962		
Belt - Fan & Gen.; Ser. No. 13949 & Before .....	316250R1	♣9490HD
Belt - Fan & Gen.; Ser. No. 13950 & After ...	382228R1	♣9520HD
Hose - Upper .....		≈<20611
Hose - Lower .....		24232
Hose - By Pass .....		28441
<b>2656 Industrial</b>		
<b>IH 6-Cyl. 263</b>		
1973-1966		
Belt - Fan .....	396829R1	♣9440HD
Belt - W.P. & Alt. ....	403617R1	♣9470HD
Hose - Upper .....		●26510
Hose - Lower .....		●26509
Hose - By Pass .....		20338
<b>IH 6-Cyl. 281 Diesel</b>		
1973-1966		
Belt - A.C. ....	395463R1	♣9620HD
Belt - Fan; W/44" Belt O.C. ....	396829R1	♣9440HD
Belt - Fan; W/48 1/4" Belt O.C. ....	378113R2	♣9480HD
Belt - Fan; W/49 1/4" Belt O.C. ....	385738R1	♣9490HD
Belt - Fan; W/51 1/4" Belt O.C. ....	396830R1	♣9510HD
Belt - W.P. & Alt./Gen. ....		♣9490HD
Hose - Upper .....		●26510
Hose - Lower .....		●26507
Hose - By Pass .....		28441
<b>2706 Industrial</b>		
<b>IH 6-Cyl. 263</b>		
1967-1963		
Belt - Fan; W/47 1/4" Belt O.C. ....	393415R1	♣9470HD
Belt - Fan; W/48 1/4" Belt O.C. ....	378113R1	♣9480HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C. ....	393415R1	♣9470HD
Belt - W.P. & Alt./Gen.; W/46 1/2" Belt O.C. ....		♣9463HD
Belt - W.P. & Gen. ....	316250R1	♣9490HD
Hose - Upper; Ser. No. 37236 & Before .....		●26510
Hose - Lower; Ser. No. 5273 & Before .....		●26509
Hose - Lower; Ser. No. 5274 & After .....		●26510
Hose - By Pass .....		20338
<b>IH 6-Cyl. 282 Diesel</b>		
1967-1963		
Belt - A.C.; W/62 1/4" Belt O.C. ....	395463R1	♣9620HD
Belt - A.C.; W/72 1/4" Belt O.C. ....	397397R1	♣9720HD
Belt - Fan; Ser. No. 49663 & Before .....	378113R1	♣9480HD
Belt - Fan; Ser. No. 49664 & After .....	385674R1	♣9490HD
Belt - W.P. & Alt.; W/64 1/4" Belt O.C. ....	396543R1	♣9640HD
Belt - W.P. & Alt./Gen.; W/49 1/4" Belt O.C. ....		♣9490HD
Hose - Upper; Ser. No. 5273 & Before .....		●26510
Hose - Upper; Ser. No. 5274 & After .....		≈<20611
		or ●26508
Hose - Lower; Ser. No. 5273 & Before .....		24232
		or ●26507
Hose - Lower; Ser. No. 5274 & After .....		●26524
Hose - By Pass .....		28441
<b>2756 Industrial</b>		
<b>IH 6-Cyl. 291</b>		
1971-1969		
Belt - Fan; W/47 1/4" Belt O.C. ....	393415R1	♣9470HD
Belt - Fan; W/48 1/4" Belt O.C. ....	378113R1	♣9480HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C. ....	393415R1	♣9470HD
Belt - W.P. & Alt./Gen.; W/46 1/2" Belt O.C. ....		♣9463HD
Belt - W.P. & Gen. ....	316250R1	♣9490HD
Hose - Lower .....		●26510
<b>IH 6-Cyl. 310 Diesel</b>		
1971-1969		
Belt - A.C. ....	395463R1	♣9620HD
Belt - Fan .....	396543R1	♣9640HD
Belt - W.P. & Alt.; W/64 1/4" Belt O.C. ....	396543R1	♣9640HD
Belt - W.P. & Alt./Gen.; W/49 1/4" Belt O.C. ....		♣9490HD

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>2756 Industrial - Continued</b>		
<b>IH 6-Cyl. 310 Diesel - Continued</b>		
1971-1969 - Continued		
Hose - Upper .....		≈<20611
		or ●26508
Hose - Lower .....		●26524
Hose - By Pass .....		24224
<b>2806 Industrial</b>		
<b>IH 6-Cyl. 301</b>		
1967-1963		
Belt - A.C. ....	395463R1	♣9620HD
Belt - Fan; W/47 1/4" Belt O.C. ....	393415R1	♣9470HD
Belt - Fan; W/48 1/4" Belt O.C. ....	378113R1	♣9480HD
Belt - W.P. & Alt.; W/47 1/4" Belt O.C. ....	393415R1	♣9470HD
Belt - W.P. & Alt./Gen.; W/46 1/2" Belt O.C. ....		♣9463HD
Hose - Lower .....		●26510
Hose - By Pass .....		20338
<b>IH 6-Cyl. 361 Diesel</b>		
1967-1963		
Belt - A.C. ....		9765
Belt - Fan & Alt. ....	385120R1	TR22664
Belt - Fan & Gen. ....	380060R1	TR22657
Hose - Upper .....		●26511
Hose - Lower .....		24224
		or ●26515
Hose - By Pass .....		24224
<b>2826 Industrial</b>		
<b>IH 6-Cyl. 358 Diesel</b>		
1971-1969		
Belt - Fan & Alt. ....	530076R1	♣9640HD
Hose - Upper .....		●26509
Hose - Lower .....		●26524
<b>2856 Industrial</b>		
<b>IH 6-Cyl. 301</b>		
1971-1967		
Belt - A.C. ....	395463R1	♣9620HD
Belt - Fan .....	403617R1	♣9470HD
Belt - W.P. & Alt. ....	403617R1	♣9470HD
Hose - Lower .....		●26510
Hose - By Pass .....		20338
<b>IH 6-Cyl. 407 Diesel</b>		
1971-1967		
Belt - A.C. ....	395462R1	9765
Belt - Fan & Alt. ....	385120R2	TR22664
Hose - Upper .....		●26511
Hose - Lower .....		●26516
Hose - By Pass .....		≈<20573
<b>3088; 3288</b>		
<b>IH 6-Cyl. 358 Diesel</b>		
1985-1981		
Belt - A.C.; W/52 3/4" Belt O.C. ....	680614R1	♣9525HD
Belt - A.C.; W/54 1/4" Belt O.C. ....	280210C2	♣9540HD
Belt - Fan & Alt. ....	80130C1	♣9640HD
<b>3388</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1981-1978		
Belt - A.C. ....	874097C1	♣9395HD
Belt - Fan & Alt. ....	532746R1	②TR22648
Hose - Upper .....		●26516
Hose - Lower - Eng. To Pipe .....		24244
<b>3400A Loader</b>		
<b>IH C175</b>		
1976-1972		
Belt - Fan & Alt. ....	532030R2	7516
Hose - Lower .....		≈<21660
		or ●25474

②Two Required ≈<Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>3400A Loader – Continued</b>		
<b>IH D179 Diesel</b>		
1976-1972		
Belt - Fan & Alt. ....	534310R1	▲9630HD
Hose - Upper .....		●26503
<b>3414 Loader</b>		
<b>IH 4-Cyl. 153 Diesel</b>		
1967-1961		
Belt - Alt. ....	401691R1	▲9341HD
Belt - Fan; W/31 3/4" Belt O.C. ....	48878D	▲9313HD
Belt - Fan; W/34 3/4" Belt O.C. ....	376371R1	TR22344
Hose - Upper .....		≧20065
		or ●25472
Hose - Lower .....		●25251
<b>IH BC144</b>		
1967-1961		
Belt - Alt. ....	401691R1	▲9341HD
Belt - Fan; W/31 3/4" Belt O.C. ....	48878D	▲9313HD
Belt - Fan; W/34 3/4" Belt O.C. ....	376371R1	TR22344
Hose - Upper .....		≧20065
		or ●25472
Hose - Lower .....		●25251
<b>3444 Loader</b>		
<b>IH 4-Cyl. 153 Diesel</b>		
1971-1967		
Belt - Alt. ....	401691R1	▲9341HD
Belt - Fan; W/31 3/4" Belt O.C. ....	48878D	▲9313HD
Belt - Fan; W/34 3/4" Belt O.C. ....	376371R1	TR22344
<b>IH BC144</b>		
1971-1967		
Belt - Alt. ....	401691R1	▲9341HD
Belt - Fan; W/31 3/4" Belt O.C. ....	48878D	▲9313HD
Belt - Fan; W/34 3/4" Belt O.C. ....	376371R1	TR22344
<b>3488</b>		
<b>IH 6-Cyl. 466 Diesel</b>		
1985-1981		
Belt - A.C.; W/40 1/2" Belt O.C. ....	242269R2	▲9400HD
Belt - A.C.; W/42" Belt O.C. ....	1250587C1	▲9415HD
Belt - W.P. & Alt. ....	532746R1	TR22648
<b>3500A Loader</b>		
<b>IH D239 Diesel</b>		
1978-1972		
Belt - Fan & Alt. ....	403303R1	7545
<b>3514 Loader</b>		
<b>IH 4-Cyl. 153</b>		
1972-1965		
Belt - Fan .....		▲9490HD
Belt - W.P. & Gen. ....	151529R1	7440
Hose - Upper .....		●26510
Hose - Lower .....		24222
Hose - By Pass .....		28439
<b>IH 4-Cyl. 175</b>		
1972-1965		
Belt - Fan & Alt. ....	403303R1	7545
<b>IH 4-Cyl. 188 Diesel</b>		
1972-1965		
Belt - Fan .....	385674R1	▲9490HD
Belt - W.P. & Gen. ....	315969R1	▲9480HD
Hose - Upper .....		●26510
Hose - Lower .....		24232
Hose - By Pass .....		20338
<b>IH 4-Cyl. 239 Diesel</b>		
1972-1965		
Belt - Fan & Alt.; W/O Syncro Mesh Trans. .	401128R1	▲9580HD
Belt - Fan & Alt.; W/Syncro Mesh Trans. ....	403303R1	7545

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>3588</b>		
<b>IH 6-Cyl. 466 Diesel</b>		
1981-1978		
Belt - A.C. ....	874097C1	▲9395HD
Belt - Fan & Alt. ....	532746R1	②TR22648
Hose - Upper .....		●26516
Hose - Lower .....		24244
<b>3688</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1985-1982		
Belt - A.C.; W/40 1/4" Belt O.C. ....	242269R2	▲9400HD
Belt - A.C.; W/41 1/4" Belt O.C. ....	288202C2	▲9412HD
Belt - A.C.; W/41 7/8" Belt O.C. ....	1250587C1	▲9415HD
Belt - Alt. ....	131201C91	TR24638
Belt - Fan .....	131201C91	TR24638
Belt - Fan & Alt. ....	532746R1	TR22648
<b>3788</b>		
<b>IH 6-Cyl. 466 Diesel</b>		
1981-1980		
Belt - A.C. ....	874097C1	▲9395HD
Belt - Fan & Alt. ....	532746R1	②TR22648
Hose - Upper .....		●26516
Hose - Lower .....		24244
<b>4100</b>		
<b>IH 6-Cyl. 429 Diesel</b>		
1968-1965		
Belt - A.C. ....	396472R1	▲9650HD
Belt - Fan .....	390460R1	TR28680
Belt - W.P. & Alt. ....	390461R1	TR22588
Hose - By Pass .....		24224
<b>4156</b>		
<b>IH 6-Cyl. 429 Diesel</b>		
1970-1969		
Belt - A.C. ....	396472R1	▲9650HD
Belt - Fan .....	390460R1	TR28680
Belt - W.P. & Alt. ....	390461R1	TR22588
Hose - Upper .....		●26532
Hose - Lower .....		24948
Hose - By Pass .....		24224
<b>4166</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1976-1972		
Belt - A.C. ....	65337C2	▲9375HD
Belt - W.P. & Alt. ....	532746R1	②TR22648
Hose - Upper .....		●26524
Hose - Lower .....		24948
<b>4300</b>		
<b>IH 6-Cyl. 817 Diesel</b>		
1970-1967		
Belt - Gen. ....	173447H1	▲9470HD
Hose - Upper .....		24946
<b>4366</b>		
<b>IH 6-Cyl. 466 Diesel</b>		
1976-1973		
Belt - A.C.; W/37 3/4" Belt O.C. ....	65337C2	▲9375HD
Belt - A.C.; W/38 3/4" Belt O.C. ....	131403C1	▲9385HD
Belt - Fan .....	532746R1	②TR22648
Hose - Upper .....		●26513
<b>4386</b>		
<b>IH 6-Cyl. 466 Diesel</b>		
1981-1976		
Belt - A.C.; Ser. No. 1499 & Before .....	65337C2	▲9375HD
Belt - A.C.; Ser. No. 1500 & After .....	131403C1	▲9385HD
Belt - Fan; Ser. No. 1499 & Before .....	532746R1	②TR22648
Belt - Fan; Ser. No. 1500 & After .....	131201C91	②TR24638
Hose - Upper .....		24236

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>4386 - Continued</b>		
<b>IH 6-Cyl. 466 Diesel - Continued</b>		
1981-1976 - Continued		
Hose - Lower .....		24240
<b>4568</b>		
<b>IH V-8 798 Diesel</b>		
1976-1975		
Belt - Alt. & A.C.; W/60 1/4" Belt O.C. ....	131304C1	②▲9600HD
Belt - Alt. & A.C.; W/62 1/4" Belt O.C. ....		②▲9620HD
Belt - Alt. & A.C.; W/63 1/4" Belt O.C. ....		②▲9630HD
Belt - Fan & W.P. ....	680600C1	③TR22648
Hose - Upper .....		24228
Hose - Lower .....		24248
<b>4586</b>		
<b>IH V-8 798 Diesel</b>		
1981-1976		
Belt - Alt. & A.C.; W/60 1/4" Belt O.C. ....	131304C1	②▲9600HD
Belt - Alt. & A.C.; W/63 1/4" Belt O.C. ....		②▲9630HD
Belt - Fan & W.P.; Ser. No. 1500 & Before ..	680600C1	④TR22648
Belt - Fan & W.P.; Ser. No. 1501 & After .....		④TR24638
Hose - Upper .....		24228
Hose - Lower .....		24248
<b>4786</b>		
<b>IH V-8 798 Diesel</b>		
1981-1978		
Belt - Alt. & A.C. ....		②▲9600HD
Belt - Fan & W.P. ....	680600C1	③TR22648
Hose - Upper .....		24228
Hose - Lower - Eng. To Pipe .....		24240
Hose - Lower - Pipe To Rad. ....		24244
<b>5088</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1985-1981		
Belt - A.C. ....	1250587C1	▲9415HD
Belt - Fan & Alt.; W/A.C. ....	65999C1	②TR24638
Belt - Fan & Alt.; W/O A.C. ....	532746R1	TR22648
<b>5288; 5488</b>		
<b>IH 6-Cyl. 466 Diesel</b>		
1985-1981		
Belt - A.C. ....	1250587C1	▲9415HD
Belt - Fan & Alt.; W/A.C. ....	65999C1	②TR24638
Belt - Fan & Alt.; W/O A.C. ....	532746R1	TR22648
<b>6388</b>		
<b>IH 6-Cyl. 436 Diesel</b>		
1985-1981		
Belt - A.C. ....		▲9415HD
Belt - Fan & Alt. ....	532746R1	②TR22648
Hose - Lower - Pipe To Rad. ....		24444
Hose - By Pass .....		21461
<b>6588; 6788</b>		
<b>IH 6-Cyl. 466 Diesel</b>		
1985-1981		
Belt - A.C. ....		▲9415HD
Belt - Fan & Alt. ....	532746R1	②TR22648
Hose - Lower - Pipe To Rad. ....		24444
Hose - By Pass .....		21461
<b>7288</b>		
<b>IH 6-Cyl. 466 Diesel</b>		
1985		
Belt - A.C. ....	164550R2	▲9425HD
Belt - Fan & Alt. ....	537072R91	②TR22648

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>7488</b>		
<b>IH 6-Cyl. 466 Diesel</b>		
1985		
Belt - A.C. ....	1250587C1	▲9415HD
Belt - Fan & Alt. ....	65999C1	②TR24638
<b>21206 Industrial</b>		
<b>IH 6-Cyl. 361 Diesel</b>		
1967-1965		
Belt - A.C. ....		9765
Belt - Fan & Alt. ....		TR22664
Hose - Lower .....		●26515
Hose - By Pass .....		≧<20267
<b>21256 Industrial</b>		
<b>IH 6-Cyl. 407 Diesel</b>		
1969-1967		
Belt - A.C. ....		▲9610HD
Belt - Fan & Alt. ....	385120R2	TR22664
<b>A Farmall</b>		
<b>IH 4-Cyl. 113</b>		
1947-1939		
Belt - Fan .....	46869D	TR26341
Belt - Gen.; W/Bosch Compr. ....	52318DA	9279
Belt - Gen.; W/Delco Compr. ....	49291D	9260
Belt - W.P. ....	48032DA	TR24379
<b>AV Farmall</b>		
<b>IH 4-Cyl. 113</b>		
1947-1941		
Belt - Fan .....	46869D	TR26341
Belt - Gen.; W/Bosch Compr. ....	52318DA	9279
Belt - Gen.; W/Delco Compr. ....	49291D	9260
Belt - W.P. ....	48032DA	TR24379
<b>B Farmall</b>		
<b>IH 4-Cyl. 113</b>		
1947-1939		
Belt - Fan .....	46869D	TR26341
Belt - Gen.; W/Bosch Compr. ....	52318DA	9279
Belt - Gen.; W/Delco Compr. ....	49291D	9260
Belt - W.P. ....	48032DA	TR24379
<b>C Farmall</b>		
<b>IH 4-Cyl. 113</b>		
1951-1948		
Belt - Fan .....	46869D	TR26341
Belt - Gen.; W/Bosch Compr. ....	52318DA	9279
Belt - Gen.; W/Delco Compr. ....	49291D	9260
Belt - W.P. ....	48032DA	TR24379
<b>Cub</b>		
<b>IH 4-Cyl. 60</b>		
1979-1964		
Belt - Fan .....	251428R1	TR24315
Belt - Gen.; Ser. No. 165153 & After .....	358213R1	2220
Belt - Gen.; Ser. No. 501 Thru 165152 .....	351321R1	6821
Hose - Upper .....		24228
Hose - Lower .....		24226
<b>Cub Farmall</b>		
<b>IH 4-Cyl. 60</b>		
1964-1947		
Belt - Fan .....	251428R1	TR24315
Belt - Gen.; Ser. No. 165153 & After .....	358213R1	2220
Belt - Gen.; Ser. No. 501 Thru 165152 .....	351321R1	6821
Hose - Upper .....		24228
Hose - Lower .....		24226

②Two Required ③Three Required ④Four Required ≧<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>Cub Lo-Boy</b>		
IH 4-Cyl. 60		
1968-1955		
Belt - Fan .....	251428R1	TR24315
<b>Cub Lo-Boy 154</b>		
IH 4-Cyl. 60		
1974-1968		
Belt - Fan & Gen. ....	527621R1	7480
<b>Cub Lo-Boy 184</b>		
IH 4-Cyl. 60		
1980-1977		
Belt - Fan & Gen. ....	527621R1	7480
<b>Cub Lo-Boy 185</b>		
IH 4-Cyl. 60		
1976-1974		
Belt - Fan & Gen. ....	527621R1	7480
<b>Cub Lo-Boy Farmall</b>		
IH 4-Cyl. 60		
1968-1955		
Belt - Fan .....	251428R1	TR24315
<b>Farmall Regular</b>		
IH 4-Cyl. 221		
1932-1924		
Belt - Fan .....	369290R1	▲9463HD
Belt - W.P. ....	304019R1	▲9490HD
<b>H Farmall</b>		
IH 4-Cyl. 152		
1953-1939		
Belt - Fan .....	368085R1	TR24379
Belt - Gen. ....	48878D	▲9313HD
Hose - Upper .....		24228
Hose - Lower .....		24224
<b>HV Farmall</b>		
IH 4-Cyl. 152		
1953-1942		
Belt - Fan .....	368085R1	TR24379
Belt - Gen. ....	48878D	▲9313HD
Hose - Upper .....		24228
Hose - Lower .....		24224
<b>I-6 McCormick-Deering</b>		
IH 4-Cyl. 248		
1953-1940		
Belt - Fan .....	16131D	TR30467
Belt - Gen.; W/Bosch Compr. ....	54857DB	9300
Belt - Gen.; W/Delco Compr. ....	49341D	▲9335HD
<b>I-9 McCormick-Deering</b>		
IH 4-Cyl. 335		
1953-1940		
Belt - Fan .....	48042D	TR30484
Belt - Gen. ....	54867D	▲9355HD
<b>ID-6 McCormick-Deering</b>		
IH 4-Cyl. 248 Diesel		
1953-1940		
Belt - Fan; W/47 1/4" Belt O.C. ....	16131D	TR30467
Belt - Fan; W/48 7/8" Belt O.C. ....	48042D	TR30484
Belt - Gen.; W/Bosch Compr. ....	54857DB	9300
Belt - Gen.; W/Delco Compr. ....	52318DA	9279
<b>ID-9 McCormick-Deering</b>		
IH 4-Cyl. 335 Diesel		
1953-1940		
Belt - Fan; W/47 1/4" Belt O.C. ....	16131D	TR30467

▲Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>ID-9 McCormick-Deering - Continued</b>		
IH 4-Cyl. 335 Diesel - Continued		
1953-1940 - Continued		
Belt - Fan; W/48 7/8" Belt O.C. ....	48042D	TR30484
Belt - Gen.; W/Bosch Compr. ....	54857DB	9300
Belt - Gen.; W/Delco Compr. ....	52318DA	9279
<b>M Farmall</b>		
IH 4-Cyl. 248		
1952-1939		
Belt - Fan .....	277448R1	TR30467
Belt - Gen.; W/Bosch Compr. ....	54867D	▲9355HD
Belt - Gen.; W/Delco Compr. ....	49341D	▲9335HD
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>MD Farmall; MDV Farmall</b>		
IH 4-Cyl. 248 Diesel		
1952-1941		
Belt - Fan .....	16131D	TR30467
Belt - Gen.; W/Bosch Compr. ....	54857DB	9300
Belt - Gen.; W/Delco Compr. ....	52318DA	9279
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>MV Farmall</b>		
IH 4-Cyl. 248		
1952-1939		
Belt - Fan .....	277448R1	TR30467
Belt - Gen.; W/Bosch Compr. ....	54867D	▲9355HD
Belt - Gen.; W/Delco Compr. ....	49341D	▲9335HD
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>O-4 McCormick</b>		
IH 4-Cyl. 152		
1953-1940		
Belt - Fan .....	48032D	TR24379
Belt - Gen. ....		▲9309HD
Hose - Upper .....		24228
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>O-6 McCormick</b>		
IH 4-Cyl. 248		
1953-1940		
Belt - Fan .....	16131D	TR30467
Belt - Gen.; W/Bosch Compr. ....	54867D	▲9355HD
Belt - Gen.; W/Delco Compr. ....	49341D	▲9335HD
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>OS-4 McCormick</b>		
IH 4-Cyl. 152		
1953-1944		
Belt - Fan .....	48032D	TR24379
Belt - Gen. ....		▲9309HD
Hose - Upper .....		24228
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>OS-6 McCormick</b>		
IH 4-Cyl. 248		
1953-1944		
Belt - Fan .....	16131D	TR30467
Belt - Gen.; W/Bosch Compr. ....	54867D	▲9355HD
Belt - Gen.; W/Delco Compr. ....	49341D	▲9335HD
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232

Agricultural Equipment





Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>Super A Farmall; Super A1 Farmall</b>		
<b>IH 4-Cyl. 113</b>		
1954-1947		
Belt - Fan .....	46869D	TR26341
Belt - Gen.; W/Bosch Compr. ....	52318DA	9279
Belt - Gen.; W/Delco Compr. ....	49291D	9260
Belt - W.P. ....	48032DA	TR24379
<b>Super C Farmall</b>		
<b>IH 4-Cyl. 123</b>		
1954-1951		
Belt - Fan .....	368084R1	TR26353
Belt - Gen.; W/Bosch Compr. ....	52318DA	9279
Belt - Gen.; W/Delco Compr. ....	49291D	9260
Belt - W.P. ....	48032DA	TR24379
<b>Super H Farmall; Super HV Farmall</b>		
<b>IH 4-Cyl. 164</b>		
1954-1952		
Belt - Fan .....	368085R1	TR24379
Belt - Gen. ....	48878D	▲9313HD
<b>Super M Farmall</b>		
<b>IH 4-Cyl. 264</b>		
1954-1952		
Belt - Fan .....	277448R1	TR30467
Belt - Gen.; W/Bosch Compr. ....	54867D	▲9355HD
Belt - Gen.; W/Delco Compr. ....	49341D	▲9335HD
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>IH 4-Cyl. 264 LPG</b>		
1954-1952		
Belt - Fan .....	277448R1	TR30467
Belt - Gen.; W/Bosch Compr. ....	54867D	▲9355HD
Belt - Gen.; W/Delco Compr. ....	49341D	▲9335HD
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>Super MD Farmall</b>		
<b>IH 4-Cyl. 264 Diesel</b>		
1954-1952		
Belt - Fan .....	16131D	TR30467
Belt - Gen.; W/Bosch Compr. ....	54857DB	9300
Belt - Gen.; W/Delco Compr. ....	52318DA	9279
<b>Super M-TA Farmall</b>		
<b>IH 4-Cyl. 264</b>		
1954		
Belt - Fan .....	69490DA	TR30467
Belt - Gen. ....	49341D	▲9335HD
Hose - Upper .....		24234
Hose - Lower .....		24232
<b>IH 4-Cyl. 264 LPG</b>		
1954		
Belt - Fan .....	69490DA	TR30467
Belt - Gen. ....	49341D	▲9335HD
Hose - Upper .....		24234
Hose - Lower .....		24232
<b>Super MV Farmall</b>		
<b>IH 4-Cyl. 264</b>		
1954-1952		
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>IH 4-Cyl. 264 LPG</b>		
1954-1952		
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>Super MV-TA Farmall</b>		
<b>IH 4-Cyl. 264</b>		
1955-1954		
Belt - Fan .....	69490DA	TR30467
Belt - Gen. ....	49341D	▲9335HD
<b>IH 4-Cyl. 264 LPG</b>		
1955-1954		
Belt - Fan .....	69490DA	TR30467
Belt - Gen. ....	49341D	▲9335HD
<b>Super W-4 McCormick</b>		
<b>IH 4-Cyl. 164</b>		
1954-1953		
Belt - Fan .....	48032D	TR24379
Belt - Gen. ....	48878D	▲9313HD
<b>Super W-6 McCormick</b>		
<b>IH 4-Cyl. 264</b>		
1954-1952		
Belt - Fan .....	69490DA	TR30467
Belt - Gen.; W/Bosch Compr. ....	54867D	▲9355HD
Belt - Gen.; W/Delco Compr. ....	49341D	▲9335HD
Hose - Upper; W/1 1/2" I.D. Hose .....		24224
Hose - Upper; W/2 1/8" I.D. Hose .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>Super W-6TA McCormick</b>		
<b>IH 4-Cyl. 264</b>		
1954		
Belt - Fan .....	69490DA	TR30467
Belt - Gen. ....	49341D	▲9335HD
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>Super WD-6 McCormick</b>		
<b>IH 4-Cyl. 264 Diesel</b>		
1954-1952		
Belt - Fan .....	69490DA	TR30467
Belt - Gen.; W/Bosch Compr. ....	52318DA	9279
Belt - Gen.; W/Delco Compr. ....	54857DB	9300
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>Super WD-9 McCormick</b>		
<b>IH 4-Cyl. 350 Diesel</b>		
1956-1953		
Belt - Fan .....	48042D	TR30484
Belt - Gen.; W/Bosch Compr. ....	52318DA	9279
Belt - Gen.; W/Delco Compr. ....	54857DB	9300
Belt - W.P. & Hyd. Pump .....	363599R1	TR28557
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>T4</b>		
<b>IH 4-Cyl. 123</b>		
1960-1959		
Belt - Fan & Gen. ....	367697R1	7417
Hose - Lower .....		24222
<b>T5</b>		
<b>IH 4-Cyl. 135</b>		
1960-1959		
Belt - Fan & Gen. ....	367697R1	7417
Hose - Lower .....		24222
<b>T6</b>		
<b>IH 4-Cyl. 248</b>		
1956-1940		
Belt - Fan .....	277448R1	TR30467

▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>T6 - Continued</b>		
<b>IH 4-Cyl. 248 - Continued</b>		
1956-1940 - Continued		
Belt - Gen. ....	49341D	▲9335HD
Hose - Upper .....		24234
Hose - Lower .....		24232
Hose - By Pass .....		24224
<b>T6 61 Series</b>		
<b>IH 4-Cyl. 264</b>		
1959-1956		
Belt - Fan .....	277448R1	TR30467
Belt - Gen. ....	54867D	▲9355HD
Hose - Upper .....		☞20206
Hose - Lower .....		24232
Hose - By Pass .....		24224
<b>T6 62 Series</b>		
<b>IH 4-Cyl. 263</b>		
1969-1959		
Belt - Fan .....	306632R1	TR28522
Belt - W.P. & Gen. ....	306910R1	TR22508
Hose - Upper .....		☞20611
		or ●26509
Hose - Lower .....		24232
		or ●26507
Hose - By Pass .....		20338
<b>T9</b>		
<b>IH 4-Cyl. 334</b>		
1956-1940		
Belt - Fan .....	48042D	TR30484
Belt - Gen.; W/Bosch Compr. ....	54857DB	9300
Belt - Gen.; W/Delco Compr. ....	54867D	▲9355HD
Hose - Upper .....		24234
Hose - Lower .....		24234
<b>T14</b>		
<b>IH 4-Cyl. 460</b>		
1950-1940		
Belt - Fan .....	30982D	TR32571
Belt - Gen. ....	54857DB	9300
<b>T18</b>		
<b>IH 4-Cyl. 221</b>		
1949-1938		
Belt - Fan .....	32542D	②TR28616
<b>T340</b>		
<b>IH 4-Cyl. 135</b>		
1964-1958		
Belt - Fan & Gen.; W/41 5/8" Belt O.C. ....	367697R1	7417
Belt - Fan & Gen.; W/42 5/8" Belt O.C. ....	610380C1	7420
Belt - Fan & Gen.; W/43 1/8" Belt O.C. ....	225532R1	7430
Hose - Lower .....		24222
Hose - By Pass .....		24224
<b>TD5</b>		
<b>IH 4-Cyl. 144 Diesel</b>		
1960-1959		
Belt - Fan .....	709502R1	TR22350
Belt - Gen. ....	704449R1	▲9309HD
Hose - Lower .....		●25251
<b>TD6</b>		
<b>IH 4-Cyl. 248 Diesel</b>		
1956-1940		
Belt - Fan .....	277448R1	TR30467
Belt - Gen.; Ser. No. 32570 & Before .....	54857DB	9300
Belt - Gen.; Ser. No. 32571 & After .....	52318DA	9279

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>TD6 61 Series</b>		
<b>IH 4-Cyl. 264 Diesel</b>		
1959-1956		
Belt - Fan .....	277448R1	TR30467
Belt - Gen.; Ser. No. 40271 & Before .....	49341D	▲9335HD
Belt - Gen.; Ser. No. 40272 & After .....		▲9319HD
Hose - Upper .....		☞20172
Hose - Lower .....		24232
Hose - By Pass .....		24224
<b>TD6 62 Series</b>		
<b>IH 6-Cyl. 282 Diesel</b>		
1969-1959		
Belt - Fan; W/O Outboard Type .....	306632R1	TR28522
Belt - Fan; W/Outboard Type .....	306633R1	TR28550
Belt - Gen. ....	306658R1	TR22514
Hose - Upper .....		☞20172
		or ●26509
Hose - Lower .....		24232
		or ●26507
Hose - By Pass .....		28441
<b>TD7E</b>		
<b>IH 4-Cyl. 239 Diesel</b>		
1988-1974		
Belt - Fan & Alt. ....	621770C1	▲9555HD
Hose - Upper .....		●26501
Hose - By Pass .....		☞20065
		or ●25526
<b>TD8E</b>		
<b>IH 4-Cyl. 239 Diesel</b>		
1987-1974		
Belt - Fan & Alt. ....	621770C1	▲9555HD
<b>TD9</b>		
<b>IH 4-Cyl. 350 Diesel</b>		
1962-1956		
Belt - Alt. ....	670572C1	TR22495
Belt - Fan .....	48042D	TR30484
Belt - Gen.; W/Bosch Compr.; W/28" Belt O.C. ....	52318DA	9279
Belt - Gen.; W/Bosch, Delco-Remy Compr.; W/30 1/4" Belt O.C. ....	54857DB	9300
Hose - Upper .....		24234
Hose - Lower .....		24234
Hose - By Pass .....		24224
<b>TD9 91 Series</b>		
<b>IH 6-Cyl. 282 Diesel</b>		
1959-1956		
Hose - Upper .....		☞20172
Hose - Lower .....		24234
Hose - By Pass .....		24224
<b>TD9 92 Series</b>		
<b>IH 6-Cyl. 282 Diesel</b>		
1962-1959		
Hose - Upper .....		24232
Hose - Lower .....		24232
		or ●26507
Hose - By Pass .....		28441
<b>TD9B</b>		
<b>IH 6-Cyl. 282 Diesel</b>		
1974-1962		
Belt - Alt. ....	670572C1	TR22495
Belt - Fan; W/Man. Trans. ....	328540R1	TR28575
Belt - Fan; W/Power Shift Trans. ....	328539R1	TR28616
Belt - Gen. ....	306658R1	TR22514
Hose - Upper .....		●26511
Hose - Lower .....		24232
		or ●26507
Hose - By Pass .....		28441

②Two Required ☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>TD12</b>		
<b>IH 6-Cyl. 466 Diesel</b>		
1994-1981		
Belt - Fan & Alt. ....		②TR22664
Hose - Upper - Eng. To Pipe .....		24236
Hose - Upper - Pipe To Rad. ....		24236
Hose - Lower .....		②21042
<b>TD14</b>		
<b>IH 4-Cyl. 460 Diesel</b>		
1958-1939		
Belt - Fan .....	30982D	TR32571
Belt - Gen .....	54857DB	9300
<b>TD14 141 Series</b>		
<b>IH 4-Cyl. 460 Diesel</b>		
1958-1939		
Hose - Upper .....		24234
Hose - Lower .....		24234
<b>TD14A</b>		
<b>IH 4-Cyl. 460 Diesel</b>		
1958-1939		
Belt - Fan .....	30982D	TR32571
Belt - Gen .....	61284D	▲9319HD
<b>TD14A 141 Series</b>		
<b>IH 4-Cyl. 460 Diesel</b>		
1958-1939		
Hose - Upper .....		24234
Hose - Lower .....		24234
<b>TD14A 142 Series</b>		
<b>IH 4-Cyl. 460 Diesel</b>		
1958-1939		
Hose - Upper .....		24238
Hose - Lower .....		24234
<b>TD15</b>		
<b>IH 6-Cyl. 534 Diesel</b>		
1966-1958		
Belt - Fan & Alt. ....		②TR22664
Belt - Fan & Gen. ....	304071R11	②TR24709
Hose - Upper - Eng. To Pipe .....		24236
Hose - Upper - Pipe To Rad. ....		24236
Hose - Lower .....		②21042
<b>TD15-150</b>		
<b>IH DT407 Diesel</b>		
1961-1958		
Belt - Fan & Gen. ....	304071R11	②TR24709
Hose - Upper .....		24238
Hose - Lower; W/Std. Cool. ....		24244
Hose - Lower - Eng. To Pipe .....		24244
Hose - Lower - Pipe To Rad. ....		24244
Hose - By Pass; W/1 3/4" I.D. Hose .....		24228
Hose - By Pass; W/2" I.D. Hose .....		24232
<b>TD15-151</b>		
<b>IH DT407 Diesel</b>		
1962-1961		
Belt - Fan & Gen. ....	304071R11	②TR24709
Hose - Upper .....		●26523
Hose - Lower - Eng. To Pipe .....		24244
Hose - Lower - Pipe To Rad. ....		24244
Hose - By Pass; W/1 3/4" I.D. Hose .....		24228
Hose - By Pass; W/2" I.D. Hose .....		24232
<b>TD15-152</b>		
<b>IH DT407 Diesel</b>		
1962-1961		
Hose - Upper .....		●26523
Hose - Lower - Eng. To Pipe .....		24244

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>TD15-152 - Continued</b>		
<b>IH DT407 Diesel - Continued</b>		
1962-1961 - Continued		
Hose - Lower - Pipe To Rad. ....		24244
Hose - By Pass; W/1 3/4" I.D. Hose .....		24228
Hose - By Pass; W/2" I.D. Hose .....		24232
<b>TD15B</b>		
<b>IH DT407 Diesel</b>		
1972-1963		
Belt - Fan & Alt. ....	612134C11	②TR24688
Belt - Fan & Gen. ....	326758R11	②TR22720
Hose - Upper .....		●26520
Hose - Lower .....		24236
Hose - By Pass .....		24224
<b>TD15C</b>		
<b>IH DT466B Diesel</b>		
1990-1972		
Belt - Fan & Alt. ....	673481C1	②TR22648
Hose - Upper .....		●26524
Hose - Lower .....		②20744
		or ●26534
<b>TD18</b>		
<b>IH 6-Cyl. 691 Diesel</b>		
1949-1938		
Belt - Fan & Gen. ....	274478R11	②CX68
<b>TD18 182 Series</b>		
<b>IH 6-Cyl. 691 Diesel</b>		
1958-1956		
Belt - Fan & Gen. ....	274478R11	②CX68
Hose - Upper .....		23557
Hose - Lower .....		24244
Hose - By Pass .....		②24228
<b>TD18A</b>		
<b>IH 6-Cyl. 691 Diesel</b>		
1955-1949		
Belt - Fan & Gen.; Ser. No. 15000 & After; W/9 1/2" C.S. Pulley .....	258275R21	②TR28649
Hose - Upper - Eng. To Pipe; Ser. No. 15001 & After .....		24238
Hose - Upper - Pipe To Rad.; Ser. No. 15001 & After .....		24238
Hose - Lower - Eng. To Pipe; Ser. No. 15001 & After .....		24238
Hose - Lower - Pipe To Rad.; Ser. No. 15001 & After .....		24238
Hose - By Pass .....		②24228
<b>TD20</b>		
<b>IH D691 Diesel</b>		
1962-1958		
Belt - Fan & Gen.; Ser. No. 3001 Thru 3145 .....	274478R11	②CX68
Belt - Fan & Gen.; Ser. No. 3146 & After ID201 .....	316317R11	②TR28706
<b>IH DT429 Diesel</b>		
1962-1958		
Belt - Fan & Gen.; Ser. No. 3001 Thru 3145 .....	274478R11	②CX68
Belt - Fan & Gen.; Ser. No. 3146 & After ID201 .....	316317R11	②TR28706
<b>IH DVT573B Diesel</b>		
1962-1958		
Belt - Fan & Gen.; Ser. No. 3001 Thru 3145 .....	274478R11	②CX68
Belt - Fan & Gen.; Ser. No. 3146 & After ID201 .....	316317R11	②TR28706
<b>TD20-200</b>		
<b>IH D691 Diesel</b>		
1961-1958		
Belt - Fan & Gen.; Ser. No. 3001 Thru 3145 .....	274478R11	②CX68

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>TD20-200 - Continued</b>		
<b>IH D691 Diesel - Continued</b>		
1961-1958 - Continued		
Belt - Fan & Gen.; Ser. No. 3146 & After		
ID201	316317R11	②TR28706
Hose - Upper		23557
<b>IH DT429 Diesel</b>		
1961-1958		
Belt - Fan & Gen.; Ser. No. 3001 Thru 3145	274478R11	②CX68
Belt - Fan & Gen.; Ser. No. 3146 & After		
ID201	316317R11	②TR28706
Hose - Upper - Eng. To Pipe		24240
Hose - Upper - Pipe To Rad.		24240
Hose - Lower - Eng. To Pipe		24248
Hose - Lower - Pipe To Rad.		24248
Hose - By Pass		24224
<b>IH DVT573B Diesel</b>		
1961-1958		
Belt - Fan & Gen.; Ser. No. 3001 Thru 3145	274478R11	②CX68
Belt - Fan & Gen.; Ser. No. 3146 & After		
ID201	316317R11	②TR28706
Hose - Upper - Eng. To Pipe		24240
Hose - Upper - Pipe To Rad.		24240
Hose - Lower - Eng. To Pipe		24248
Hose - Lower - Pipe To Rad.		24248
Hose - By Pass		24224
<b>TD20-201</b>		
<b>IH D691 Diesel</b>		
1963-1961		
Belt - Fan & Gen.; Ser. No. 3001 Thru 3145	274478R11	②CX68
Belt - Fan & Gen.; Ser. No. 3146 & After		
ID201	316317R11	②TR28706
Hose - Upper		23557
<b>IH DT429 Diesel</b>		
1963-1961		
Belt - Fan & Gen.; Ser. No. 3001 Thru 3145	274478R11	②CX68
Belt - Fan & Gen.; Ser. No. 3146 & After		
ID201	316317R11	②TR28706
Hose - Upper - Eng. To Pipe		24240
Hose - Upper - Pipe To Rad.		24240
Hose - Lower - Eng. To Pipe		24248
Hose - Lower - Pipe To Rad.		24248
Hose - By Pass		24224
<b>IH DVT573B Diesel</b>		
1963-1961		
Belt - Fan & Gen.; Ser. No. 3001 Thru 3145	274478R11	②CX68
Belt - Fan & Gen.; Ser. No. 3146 & After		
ID201	316317R11	②TR28706
Hose - Upper - Eng. To Pipe		24240
Hose - Upper - Pipe To Rad.		24240
Hose - Lower - Eng. To Pipe		24248
Hose - Lower - Pipe To Rad.		24248
Hose - By Pass		24224
<b>TD20B</b>		
<b>IH DT429 Diesel</b>		
1970-1963		
Belt - Fan & Alt.	670741C1	②TR22570
Belt - Fan & Gen.	326998R1	③TR22570
Belt - W.P.	328502R1	TR22485
Hose - Upper - Eng. To Pipe		24240
Hose - Upper - Pipe To Rad.		24240
Hose - Lower - Eng. To Pipe		24248
Hose - Lower - Pipe To Rad.		24248
Hose - By Pass		24224

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>TD20C</b>		
<b>IH DV573B Diesel</b>		
1975-1970		
Belt - Alt.; Ser. No. 7499 & Before		TR22448
Belt - Alt.; Ser. No. 7500 & After	673947C1	▲9447HD
Hose - Upper - Eng. To Pipe		24228
Hose - Upper - Pipe To Rad.		24228
Hose - Lower - Eng. To Pipe		24248
Hose - Lower - Pipe To Rad.		24248
<b>TD24</b>		
<b>IH 6-Cyl. 1091 Diesel</b>		
1959-1947		
Hose - Upper - Eng. To Pipe		24246
Hose - Upper - Pipe To Rad.		24246
Hose - Lower - Eng. To Pipe		24246
Hose - Lower - Pipe To Rad.		24246
Hose - By Pass		24236
<b>TD25</b>		
<b>IH DT817 Diesel</b>		
1962-1959		
Belt - Fan & Gen.	310081R2	▲9480HD
Belt - Gen.	323987R1	▲9465HD
Hose - Upper		23572
Hose - Lower		24256
Hose - By Pass		24236
<b>TD25B</b>		
<b>IH DT817 Diesel</b>		
1972-1962		
Belt - Alt.	670464C1	TR22578
Belt - Gen.	403348R1	▲9463HD
Hose - Upper		23572
Hose - Lower		24256
Hose - By Pass		24236
<b>TD25C</b>		
<b>IH DT817 Diesel</b>		
1978-1968		
Belt - Alt.	670582C1	TR22517
Belt - Fan	688192C91	②TR22792
Hose - Upper - Eng. To Pipe		24446
Hose - Upper - Pipe To Rad.		24446
Hose - Lower - Eng. To Pipe		24442
Hose - Lower - Eng. To Tee		24456
Hose - Lower - Pipe To Tee		24436
Hose - Lower - Tee To Rad.		24456
<b>TD30</b>		
<b>IH DT817 Diesel</b>		
1967-1962		
Belt - Fan & Gen.	323987R1	▲9465HD
Hose - Lower		24256
Hose - By Pass		24236
<b>TD340</b>		
<b>IH 4-Cyl. 166 Diesel</b>		
1964-1958		
Belt - Fan & Gen.	315969R1	▲9490HD
Hose - Upper		②20206
		or ●26507
Hose - By Pass		20338
<b>W-4 McCormick</b>		
<b>IH 4-Cyl. 152</b>		
1953-1940		
Belt - Fan	48032D	TR24379
Belt - Gen.	61284D	▲9319HD
Hose - Upper		24228
Hose - Lower - Eng. To Pipe		24224
Hose - Lower - Pipe To Rad.		24224

②Two Required ③Three Required <Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>W-6 McCormick</b>		
<b>IH 4-Cyl. 248</b>		
1953-1940		
Belt - Fan .....	69490DA	TR30467
Belt - Gen.; W/Bosch Compr. ....	54867D	▲9355HD
Belt - Gen.; W/Delco Compr. ....	49341D	▲9335HD
Hose - Upper; W/1 1/2" I.D. Hose .....		24224
Hose - Upper; W/2 1/8" I.D. Hose .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>W-9 McCormick-Deering</b>		
<b>IH 4-Cyl. 335</b>		
1953-1940		
Belt - Fan .....	48042D	TR30484
Belt - Gen. ....	54867D	▲9355HD
Hose - Upper; W/1 1/2" I.D. Hose .....		24224
Hose - Upper; W/2" I.D. Hose .....		24232
Hose - Lower .....		24232
<b>W-14 McCormick-Deering</b>		
<b>IH 4-Cyl. 113</b>		
1939-1938		
Belt - Fan .....	48032D	TR24379
Belt - Gen. ....	61284D	▲9319HD
<b>W-400</b>		
<b>IH 4-Cyl. 264</b>		
1956-1955		
Belt - Fan .....	16131DA	TR28454
Belt - Gen. ....	49341D	▲9335HD
Belt - P.S. ....	363197R2	TR24500
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>IH 4-Cyl. 264 Diesel</b>		
1956-1955		
Belt - Fan .....	69490DA	TR30467
Belt - Gen. ....	52318DA	9279
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>IH 4-Cyl. 264 LPG</b>		
1956-1955		
Belt - Fan .....	16131DA	TR28454
Belt - Gen. ....	49341D	▲9335HD
Belt - P.S. ....	363197R2	TR24500
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>W-450</b>		
<b>IH 4-Cyl. 281</b>		
1958-1956		
Belt - Fan .....	16131DA	TR28454
Belt - Gen. ....	49341D	▲9335HD
Belt - P.S. ....	363197R2	TR24500
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>IH 4-Cyl. 281 Diesel</b>		
1958-1956		
Belt - Fan .....	69490DA	TR30467
Belt - Gen. ....	52318DA	9279
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>IH 4-Cyl. 281 LPG</b>		
1958-1956		
Belt - Fan .....	16131DA	TR28454
Belt - Gen. ....	49341D	▲9335HD
Belt - P.S. ....	363197R2	TR24500

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>W-450 - Continued</b>		
<b>IH 4-Cyl. 281 LPG - Continued</b>		
1958-1956 - Continued		
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>WD-6 McCormick</b>		
<b>IH 4-Cyl. 248 Diesel</b>		
1953-1940		
Belt - Fan .....	69490DA	TR30467
Belt - Gen.; W/Bosch Compr. ....	52318DA	9279
Belt - Gen.; W/Delco Compr. ....	54857DB	9300
Hose - Upper .....		24234
Hose - Lower - Eng. To Pipe .....		24232
Hose - Lower - Pipe To Rad. ....		24232
<b>WD-9 McCormick-Deering</b>		
<b>IH 4-Cyl. 335 Diesel</b>		
1953-1940		
Belt - Fan .....	48042D	TR30484
Belt - Gen.; W/Bosch Compr.; Ser. No. 501 & Before .....	54857DB	9300
Belt - Gen.; W/Bosch Compr.; Ser. No. 502 & After .....	52318DA	9279
Belt - Gen.; W/Delco Compr. ....	54857DB	9300
Hose - Upper .....		24240
Hose - Lower .....		24232
<b>WDR-9 McCormick-Deering</b>		
<b>IH 4-Cyl. 335 Diesel</b>		
1953-1945		
Belt - Fan .....	48042D	TR30484
Belt - Gen. ....	52318DA	9279
<b>WR-9 McCormick-Deering</b>		
<b>IH 4-Cyl. 335</b>		
1953-1940		
Belt - Fan .....	48042D	TR30484
Belt - Gen. ....	54867D	▲9355HD
<b>IH 4-Cyl. 335 Distillate</b>		
1953-1940		
Belt - Fan .....	48042D	TR30484
Belt - Gen. ....	54867D	▲9355HD
<b>JCB</b>		
<b>Fastrac 8250</b>		
<b>Cummins 6-Cyl. 505 Diesel</b>		
2008-2007		
Belt - Serpentine .....	3289746	▲K080785HD
Belt - A.C. ....		▲9390HD
<b>JOHN DEERE</b>		
<b>40</b>		
<b>John Deere 2-Cyl. 101</b>		
1955-1953		
Belt - Fan .....	M1900T	7360
Belt - Gen. ....	M1862T	7250
<b>50</b>		
<b>John Deere 2-Cyl. 190</b>		
1956-1952		
Belt - W.P. & Gen.; Ser. No. 5016057 & Before .....	B2893R	▲9405HD
Belt - W.P. & Gen.; Ser. No. 5016058 & After .....	B3288R	7395
<b>John Deere 2-Cyl. 190 LPG</b>		
1956-1952		
Belt - W.P. & Gen.; Ser. No. 5016057 & Before .....	B2893R	▲9405HD

▲Standard Belt May Also Be Available

Agricultural Equipment





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>50 - Continued</b>		
<b>John Deere 2-Cyl. 190 LPG - Continued</b>		
1956-1952 - Continued		
Belt - W.P. & Gen.; Ser. No. 5016058 & After .....	B3288R	7395
<b>60</b>		
<b>John Deere 2-Cyl. 321</b>		
1956-1952		
Belt - W.P. & Gen.; Ser. No. 602999 & Before .....	A4287R	◆9463HD
Belt - W.P. & Gen.; Ser. No. 603000 & After .....	A4897R	7450
<b>John Deere 2-Cyl. 321 LPG</b>		
1956-1952		
Belt - W.P. & Gen.; Ser. No. 602999 & Before .....	A4287R	◆9463HD
Belt - W.P. & Gen.; Ser. No. 603000 & After .....	A4897R	7450
<b>70</b>		
<b>John Deere 2-Cyl. 376 Diesel</b>		
1956-1953		
Belt - W.P. & Gen.; Ser. No. 7008099 & Before .....	A4287R	◆9463HD
Belt - W.P. & Gen.; Ser. No. 7008100 & After .....	A4897R	7450
<b>John Deere 2-Cyl. 380</b>		
1956-1953		
Belt - W.P. & Gen.; Ser. No. 7008099 & Before .....	A4287R	◆9463HD
Belt - W.P. & Gen.; Ser. No. 7008100 & After .....	A4897R	7450
<b>John Deere 2-Cyl. 380 LPG</b>		
1956-1953		
Belt - W.P. & Gen.; Ser. No. 7008099 & Before .....	A4287R	◆9463HD
Belt - W.P. & Gen.; Ser. No. 7008100 & After .....	A4897R	7450
<b>80</b>		
<b>John Deere 2-Cyl. 472 Diesel</b>		
1956-1955		
Belt - Fan & Gen. ....	R1561R	7530
Belt - W.P. ....	R1528R	6720
<b>300 Tractor</b>		
<b>John Deere 3-Cyl. 135</b>		
1979-1975		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Upper .....		●25477
Hose - Lower .....		●26502
<b>John Deere 3-Cyl. 152 Diesel</b>		
1977-1968		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Lower .....		●26502
Hose - By Pass .....		28439
<b>300B Industrial</b>		
<b>John Deere 3-Cyl. 152 Diesel</b>		
1981-1968		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Upper .....		≅20065
		or ●25473
<b>301</b>		
<b>John Deere 3-Cyl. 135</b>		
1974-1971		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Upper .....		●25477
Hose - Lower .....		●26502

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>301 - Continued</b>		
<b>John Deere 3-Cyl. 152 Diesel</b>		
1975-1974		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Lower .....		●26502
Hose - By Pass .....		28439
<b>301A</b>		
<b>John Deere 3-Cyl. 135</b>		
1979-1974		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Upper .....		20450
		or ●25474
Hose - Lower .....		●26502
<b>John Deere 3-Cyl. 152 Diesel</b>		
1981-1974		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Upper .....		●25477
Hose - By Pass .....		28439
<b>302 Industrial</b>		
<b>John Deere 3-Cyl. 147</b>		
1981-1974		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Upper .....		20450
		or ●25474
Hose - Lower .....		●26502
<b>John Deere 3-Cyl. 164 Diesel</b>		
1981-1974		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Upper .....		●25477
Hose - By Pass .....		28439
<b>320</b>		
<b>John Deere 2-Cyl. 101</b>		
1958-1956		
Belt - Fan .....	M1900T	7360
Belt - Gen. ....	M1862T	7250
Hose - Upper .....		24236
Hose - Lower .....		②24232
<b>330 Tractor</b>		
<b>John Deere 2-Cyl. 101</b>		
1960-1958		
Belt - Fan .....	M1900T	7360
Belt - Gen. ....	M1862T	7250
Hose - Upper .....		24236
Hose - Lower .....		②24232
<b>350</b>		
<b>John Deere 3-Cyl. 152</b>		
1970-1964		
Belt - Fan & Alt.; W/50" Belt O.C. ....	T20161	TR22495
Belt - Fan & Alt.; W/51 1/4" Belt O.C. ....	T24757	TR22508
Belt - Fan & Alt.; W/51 7/8" Belt O.C. ....	T24473	TR22514
<b>John Deere 3-Cyl. 152 Diesel</b>		
1970-1964		
Belt - Fan & Alt.; W/50" Belt O.C. ....	T20161	TR22495
Belt - Fan & Alt.; W/51 1/4" Belt O.C. ....	T24757	TR22508
Belt - Fan & Alt.; W/51 7/8" Belt O.C. ....	T24473	TR22514
<b>350C</b>		
<b>John Deere 3-Cyl. 152 Diesel</b>		
1986-1975		
Hose - Upper .....		●25476
Hose - By Pass .....		28439
<b>John Deere 3-Cyl. 164 Diesel</b>		
1986-1975		
Belt - Fan & Alt.; W/50" Belt O.C. ....	T20161	TR22495
Belt - Fan & Alt.; W/51 1/4" Belt O.C. ....	T24757	TR22508
Belt - Fan & Alt.; W/51 7/8" Belt O.C. ....	T24473	TR22514

②Two Required ≅Cut to Fit ●Flexible Coolant Hose ◆Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>350C - Continued</b>		
<b>John Deere 3-Cyl. 164 Diesel - Continued</b>		
1986-1975 - Continued		
Hose - Upper .....		●25476
Hose - By Pass .....		28439
<b>400 Industrial</b>		
<b>John Deere 4-Cyl. 180</b>		
1979-1975		
Belt - Fan & Alt. .... T20334T		TR22474
Hose - Upper .....		●25474
Hose - Lower .....		●26603
<b>John Deere 4-Cyl. 219 Diesel</b>		
1985-1975		
Belt - Fan & Alt. .... T20334T		TR22474
Hose - Upper .....		●25477
Hose - Lower .....		●26502
<b>400G</b>		
<b>John Deere 4-Cyl. 239 Diesel</b>		
1997-1988		
Hose - Upper .....		≈21794
<b>401 Industrial</b>		
<b>John Deere 4-Cyl. 180</b>		
1974-1968		
Belt - Fan & Alt. .... T20334T		TR22474
Hose - Upper .....		●25476
<b>John Deere 4-Cyl. 219 Diesel</b>		
1974-1968		
Belt - Fan & Alt. .... T20334T		TR22474
Hose - Upper .....		●25477
Hose - By Pass .....		28439
<b>401B Industrial</b>		
<b>John Deere 4-Cyl. 180</b>		
1981-1979		
Belt - Fan & Alt.; W/50" Belt O.C. .... T20161		TR22495
Belt - Fan & Alt.; W/51 1/4" Belt O.C. .... T24757		TR22508
Belt - Fan & Alt.; W/51 7/8" Belt O.C. .... T24473		TR22514
<b>John Deere 4-Cyl. 219 Diesel</b>		
1981-1979		
Belt - Fan & Alt.; W/50" Belt O.C. .... T20161		TR22495
Belt - Fan & Alt.; W/51 1/4" Belt O.C. .... T24757		TR22508
Belt - Fan & Alt.; W/51 7/8" Belt O.C. .... T24473		TR22514
Hose - Upper .....		●25476
<b>401C Industrial</b>		
<b>John Deere 4-Cyl. 239 Diesel</b>		
1983-1974		
Belt - Fan & Alt. .... T20334T		TR22474
<b>420</b>		
<b>John Deere 2-Cyl. 113</b>		
1958-1956		
Belt - Fan .....	M3055T	TR22358
Belt - Gen. ....	M1862T	7250
Belt - P.S.; Ser. No. 131818 Thru 158074 ...	T10552T	7312
Belt - P.S.; Ser. No. 158075 & After .....	T12267T	7335
Hose - Upper .....		≈20945
		or ●25472
Hose - Lower .....		24224
Hose - By Pass .....		28439
<b>John Deere 2-Cyl. 113 LPG</b>		
1958-1956		
Belt - Fan .....	M3055T	TR22358
Belt - Gen. ....	M1862T	7250
Belt - P.S.; Ser. No. 131818 Thru 158074 ...	T10552T	7312
Belt - P.S.; Ser. No. 158075 & After .....	T12267T	7335

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>420C</b>		
<b>John Deere 2-Cyl. 113</b>		
1958-1956		
Hose - Upper .....		≈20945
		or ●25472
Hose - Lower .....		24224
Hose - By Pass .....		28439
<b>430</b>		
<b>John Deere 2-Cyl. 113</b>		
1960-1958		
Belt - Fan .....	M3055T	TR22358
Belt - Gen. ....	M1862T	7250
Belt - P.S.; Ser. No. 131818 Thru 158074 ...	T10552T	7312
Belt - P.S.; Ser. No. 158075 & After .....	T12267T	7335
Hose - Upper .....		≈20945
		or ●25472
Hose - Lower .....		24224
Hose - By Pass .....		28439
<b>John Deere 2-Cyl. 113 LPG</b>		
1960-1958		
Belt - Fan .....	M3055T	TR22358
Belt - Gen. ....	M1862T	7250
Belt - P.S.; Ser. No. 131818 Thru 158074 ...	T10552T	7312
Belt - P.S.; Ser. No. 158075 & After .....	T12267T	7335
<b>430C</b>		
<b>John Deere 2-Cyl. 113</b>		
1960-1958		
Hose - Upper .....		≈20945
		or ●25472
Hose - Lower .....		24224
Hose - By Pass .....		28439
<b>435</b>		
<b>GM 2-Cyl. 106 Diesel</b>		
1960-1959		
Belt - Fan .....	5124814	7365
Belt - W.P. & Gen. ....	5124512	7435
<b>440</b>		
<b>GM 2-Cyl. 106 Diesel</b>		
1960-1958		
Belt - Fan .....	5124814	7365
Belt - P.S. ....		7290
Belt - W.P. & Gen.; Ser. No. 450782 & Before .....	5121847	7340
Belt - W.P. & Gen.; Ser. No. 450783 & After .....	5124512	7435
Hose - Lower .....		●26601
<b>John Deere 2-Cyl. 113</b>		
1960-1958		
Belt - Fan .....	M3055T	TR22358
Belt - Gen. ....	M1862T	7250
Belt - P.S.; Ser. No. 455701 & Before .....	T10552T	7312
Belt - P.S.; Ser. No. 455702 & After .....	T12267T	7335
Hose - Upper .....		≈20945
		or ●25472
Hose - Lower .....		24224
Hose - By Pass .....		28439
<b>440C</b>		
<b>John Deere 2-Cyl. 113</b>		
1961-1958		
Hose - Upper .....		≈20945
		or ●25472
Hose - Lower .....		24224
Hose - By Pass .....		28439
<b>John Deere 2-Cyl. 113 Diesel</b>		
1961-1958		
Belt - Fan .....	5123192	7475
Belt - W.P. & Gen.; Ser. No. 206717 & Before .....	5121847	7340

≈Cut to Fit ●Flexible Coolant Hose



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>440C - Continued</b>		
<b>John Deere 2-Cyl. 113 Diesel - Continued</b>		
1961-1958 - Continued		
Belt - W.P. & Gen.; Ser. No. 206718 & After .....	5124432	7312
Hose - Lower .....		●26601
<b>450</b>		
<b>John Deere 4-Cyl. 180</b>		
1970-1964		
Belt - Fan & Alt.; W/50" Belt O.C. ....	T20161	TR22495
Belt - Fan & Alt.; W/51 1/4" Belt O.C. ....	T24757	TR22508
Belt - Fan & Alt.; W/51 7/8" Belt O.C. ....	T24473	TR22514
<b>John Deere 4-Cyl. 202</b>		
1970-1964		
Belt - Fan; Ser. No. 13560 & Before .....	T20161	TR22495
Belt - Fan; Ser. No. 13561 Thru 15484 .....	T24473	TR22514
Belt - Fan; Ser. No. 15485 & After .....	T24757	TR22508
<b>John Deere 4-Cyl. 202 Diesel</b>		
1970-1964		
Belt - Fan; Ser. No. 13560 & Before .....	T20161	TR22495
Belt - Fan; Ser. No. 13561 Thru 15484 .....	T24473	TR22514
Belt - Fan; Ser. No. 15485 & After .....	T24757	TR22508
Belt - Fan & Alt.; W/50" Belt O.C. ....	T20161	TR22495
Belt - Fan & Alt.; W/51 1/4" Belt O.C. ....	T24757	TR22508
Belt - Fan & Alt.; W/51 7/8" Belt O.C. ....	T24473	TR22514
<b>450C</b>		
<b>John Deere 4-Cyl. 219 Diesel</b>		
1985-1974		
Belt - Fan; Ser. No. 13560 & Before .....	T20161	TR22495
Belt - Fan; Ser. No. 13561 Thru 15484 .....	T24473	TR22514
Belt - Fan; Ser. No. 15485 & After .....	T24757	TR22508
Hose - Upper .....		≧20065
Hose - Lower .....		●26601
<b>500 Industrial</b>		
<b>John Deere 4-Cyl. 241</b>		
1967-1963		
Belt - Fan & Gen. ....	AR32659R	7555
Hose - Upper .....		●26509
Hose - Lower .....		20590
<b>John Deere 4-Cyl. 270 Diesel</b>		
1967-1963		
Belt - Fan & Gen. ....	AR32661R	7560
Hose - Upper .....		●26509
Hose - Lower .....		20590
<b>520</b>		
<b>John Deere 2-Cyl. 190</b>		
1958-1956		
Belt - W.P. & Gen. ....	B3288R	7395
Hose - Lower .....		②24230
<b>John Deere 2-Cyl. 190 LPG</b>		
1958-1956		
Belt - W.P. & Gen. ....	B3288R	7395
Hose - Lower .....		②24230
<b>530</b>		
<b>John Deere 2-Cyl. 190</b>		
1960-1958		
Belt - W.P. & Gen. ....	B3288R	7395
Hose - Lower .....		②24230
<b>John Deere 2-Cyl. 190 LPG</b>		
1960-1958		
Belt - W.P. & Gen. ....	B3288R	7395
Hose - Lower .....		②24230

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>600 Tractor</b>		
<b>John Deere 4-Cyl. 341</b>		
1970-1964		
Belt - Fan & Alt./Gen. ....	AR32659R	②7555
Hose - Upper .....		●26509
Hose - Lower .....		20590
<b>John Deere 6-Cyl. 404 Diesel</b>		
1970-1964		
Belt - Fan & Alt./Gen.; W/56 5/8" Belt O.C. ...	AR41576	②7560
Belt - Fan & Alt./Gen.; W/57 5/8" Belt O.C. ...	AR41629	②7570
<b>620</b>		
<b>John Deere 2-Cyl. 303</b>		
1958-1956		
Belt - W.P. & Gen. ....	A4897R	7450
Hose - Lower .....		24234
<b>John Deere 2-Cyl. 303 LPG</b>		
1958-1956		
Belt - W.P. & Gen. ....	A4897R	7450
Hose - Lower .....		24234
<b>630</b>		
<b>John Deere 2-Cyl. 303</b>		
1960-1958		
Belt - W.P. & Gen. ....	A4897R	7450
Hose - Lower .....		24234
<b>John Deere 2-Cyl. 303 LPG</b>		
1960-1958		
Belt - W.P. & Gen. ....	A4897R	7450
Hose - Lower .....		24234
<b>650</b>		
<b>Yanmar 2-Cyl. 52 Diesel</b>		
1989-1981		
Belt - Fan & Alt. ....	CH15509	♣9360HD
Hose - Lower .....		24220
Hose - Lower - W.P. To Rad. ....		≧20940
<b>655</b>		
<b>Yanmar 3-Cyl. 40 Diesel</b>		
1990-1986		
Belt - Fan & Alt. ....	M800313	7345
<b>670</b>		
<b>Yanmar 3-Cyl. 54 Diesel</b>		
1997-1989		
Belt - Fan & Alt. ....	M811284	7360
<b>700 Industrial</b>		
<b>John Deere 6-Cyl. 531 Diesel</b>		
1965		
Belt - Fan & Alt.; W/47 7/8" Belt O.C. ....	T20334	TR22474
Belt - Fan & Alt.; W/61 1/8" Belt O.C. ....		②7612
Hose - Upper .....		24232
Hose - Lower .....		●26526
<b>720</b>		
<b>John Deere 2-Cyl. 361</b>		
1958-1956		
Belt - W.P. & Gen. ....	A4897R	7450
<b>John Deere 2-Cyl. 361 LPG</b>		
1958-1956		
Belt - W.P. & Gen. ....	A4897R	7450

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>720 - Continued</b>		
<b>John Deere 2-Cyl. 376 Diesel</b>		
1958-1956		
Belt - W.P. & Gen. ....	A4897R	7450
<b>730</b>		
<b>John Deere 2-Cyl. 361</b>		
1961-1958		
Belt - W.P. & Gen. ....	A4897R	7450
<b>John Deere 2-Cyl. 361 LPG</b>		
1961-1958		
Belt - W.P. & Gen. ....	A4897R	7450
<b>John Deere 2-Cyl. 376 Diesel</b>		
1961-1958		
Belt - W.P. & Gen. ....	A4897R	7450
<b>750</b>		
<b>Yanmar 3-Cyl. 78 Diesel</b>		
1989-1981		
Belt - Fan & Alt. ....	CH15509	▲9360HD
Hose - Lower ....		24220
Hose - Lower - W.P. To Rad. ....		☞20940
<b>755</b>		
<b>Yanmar 3-Cyl. 54 Diesel</b>		
1999-1986		
Belt - Fan & Alt. ....	M800313	7345
<b>760 Industrial</b>		
<b>John Deere 6-Cyl. 531 Diesel</b>		
1968-1965		
Belt - Fan & Alt.; W/47 7/8" Belt O.C. ....	T20334	TR22474
Belt - Fan & Alt.; W/61 1/8" Belt O.C. ....		②7612
Hose - Upper ....		24232
Hose - Lower ....		●26526
<b>770</b>		
<b>Yanmar 3-Cyl. 83 Diesel</b>		
1998		
Belt - Fan & Alt. ....	M808685	▲9412HD
Hose - Upper ....	M802686	●25251
Hose - Lower ....	M802634	●25154
1997-1989		
Belt - Fan & Alt. ....		▲9412HD
Hose - Upper ....		●25251
Hose - Lower ....		●25154
<b>790</b>		
<b>Yanmar 3-Cyl. 81 Diesel</b>		
1998		
Belt - Fan & Alt. ....		▲9412HD
<b>Yanmar 3-Cyl. 91 Diesel</b>		
2008-2006		
Belt - Fan & Alt. ....	M801821	▲9390HD
2005-1999		
Belt - Fan & Alt. ....		▲9412HD
<b>820</b>		
<b>John Deere 2-Cyl. 472 Diesel</b>		
1958-1956		
Belt - Fan & Alt./Gen.; Ser. No. 75344 & Before ....	T23505	TR22461
Belt - Fan & Alt./Gen.; Ser. No. 75345 & After ....	T20334	TR22474
Hose - Lower ....		24234
<b>John Deere 3-Cyl. 152 Diesel</b>		
1975-1968		
Belt - Fan & Alt./Gen.; Ser. No. 75344 & Before ....	T23505	TR22461

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>820 - Continued</b>		
<b>John Deere 3-Cyl. 152 Diesel - Continued</b>		
1975-1968 - Continued		
Belt - Fan & Alt./Gen.; Ser. No. 75345 & After ....	T20334	TR22474
Hose - Lower ....		24234
<b>830</b>		
<b>John Deere 2-Cyl. 472 Diesel</b>		
1960-1958		
Hose - Lower ....		24234
<b>John Deere 3-Cyl. 152 Diesel</b>		
1975-1974		
Belt - Fan & Alt. ....	T20334	TR22474
Belt - Fan & Gen. ....	R1561R	7530
Belt - W.P. ....	R1528R	6720
Hose - Lower ....		24234
<b>840</b>		
<b>John Deere 2-Cyl. 472 Diesel</b>		
1960-1958		
Belt - Fan & Gen.; Ser. No. 8400199 & Before ....	R1561R	7530
Belt - Fan & Gen.; Ser. No. 8400200 & After ....	R21525R	7541
Belt - W.P. ....	R1528R	6720
Hose - Lower ....		24234
<b>850</b>		
<b>Yanmar 3-Cyl. 78 Diesel</b>		
1989-1978		
Belt - Fan & Alt.; Ser. No. 007760 & Before ....		▲9375HD
Belt - Fan & Alt.; Ser. No. 007761 & After ....	CH14022	▲9400HD
Belt - Fan & Alt.; W/36 1/4" Belt O.C. ....		▲9360HD
Hose - Lower ....		24220
<b>850B</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1994-1985		
Belt - Fan ....	AT31010	③▲9620HD
Belt - Fan To Alt. ....		▲9350HD
Hose - Upper ....		●26532
<b>855</b>		
<b>Yanmar 3-Cyl. 61 Diesel</b>		
1999		
Belt - Fan & Alt. ....	M805441	▲9385HD
Hose - Upper ....	M92621	●25150
1998-1986		
Belt - Fan & Alt. ....	M805441	▲9385HD
Hose - Upper ....		●25150
<b>870</b>		
<b>Yanmar 3-Cyl. 87 Diesel</b>		
1999-1998		
Belt - Fan & Alt. ....	M808685	▲9412HD
1997-1989		
Belt - Fan & Alt. ....		▲9412HD
<b>900HC</b>		
<b>Yanmar 3-Cyl. 78 Diesel</b>		
1990-1986		
Belt - Fan & Alt. ....		▲9405HD
Hose - Upper ....		●25150
Hose - Lower ....		●25150
<b>950</b>		
<b>Yanmar 3-Cyl. 105 Diesel</b>		
1989-1978		
Belt - Fan & Alt.; Ser. No. 010859 & Before .	CH10367	▲9380HD
Belt - Fan & Alt.; Ser. No. 010860 & After ....	CH12865	▲9412HD
Hose - Upper ....		●25150

②Two Required ③Three Required ☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>950 - Continued</b>		
<b>Yanmar 3-Cyl. 105 Diesel - Continued</b>		
1989-1978 - Continued		
Hose - Lower .....		●25150
<b>955</b>		
<b>Yanmar 3-Cyl. 87 Diesel</b>		
1999-1990		
Belt - Fan & Alt. ....	M805011	▲9375HD
<b>970</b>		
<b>Yanmar 4-Cyl. 111 Diesel</b>		
1998-1989		
Belt - Fan & Alt. ....	M808685	▲9412HD
Hose - Upper .....	M804390	●25474
<b>990</b>		
<b>Yanmar 4-Cyl. 121 Diesel</b>		
2008-2000		
Belt - Fan .....	M808685	▲9412HD
<b>1010</b>		
<b>John Deere 4-Cyl. 115</b>		
1965-1960		
Belt - Fan & Gen. ....	T11961T	7435
Hose - Upper .....		≧20065
		or ●25472
Hose - Lower .....		24224
<b>John Deere 4-Cyl. 145 Diesel</b>		
1965-1960		
Belt - Fan & Gen. ....	T12530T	7440
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>1020</b>		
<b>John Deere 3-Cyl. 135</b>		
1973-1965		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Upper; W/Hi-Low Power Shift Trans. ....		●25474
Hose - Upper; W/O Hi-Low Power Shift Trans. ....		●25477
Hose - Lower .....		21182
		or ●26603
<b>John Deere 3-Cyl. 152 Diesel</b>		
1973-1965		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Lower .....		21182
		or ●26502
<b>1050</b>		
<b>Yanmar 3-Cyl. 105 Diesel</b>		
1989-1988		
Belt - Fan & Alt.; W/41 1/2" Belt O.C. ....	M808685	▲9412HD
Belt - Fan & Alt.; W/49 1/4" Belt O.C. ....		▲9490HD
Hose - Upper .....		●25150
Hose - Lower .....		●25150
1987-1980		
Belt - Fan & Alt.; W/41 1/4" Belt O.C. ....	CH12865	▲9412HD
Belt - Fan & Alt.; W/49 1/4" Belt O.C. ....		▲9490HD
Hose - Upper .....		●25150
Hose - Lower .....		●25150
<b>1070</b>		
<b>Yanmar 4-Cyl. 116 Diesel</b>		
1998-1997		
Belt - Fan & Alt.; W/41 1/2" Belt O.C. ....	M808685	▲9412HD
1996-1989		
Belt - Fan & Alt. ....	M808685	▲9412HD
Hose - Upper .....	M804390	●25474

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>1120</b>		
<b>John Deere 3-Cyl. 135 Diesel</b>		
1973		
Belt - Fan & Alt. ....		7320
<b>1250</b>		
<b>Yanmar 3-Cyl. 143 Diesel</b>		
1989-1982		
Belt - Fan & Alt. ....	CH16856	▲9465HD
Hose - Upper .....		●25478
<b>1450</b>		
<b>Yanmar 4-Cyl. 190 Diesel</b>		
1988-1984		
Belt - Fan & Alt. ....	CH16856	▲9465HD
Hose - Upper .....		≧21660
		or ●25474
Hose - Lower .....		●25476
<b>1520</b>		
<b>John Deere 3-Cyl. 165</b>		
1973-1968		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Upper; W/12" Hose .....		●25474
Hose - Upper; W/17" Hose .....		●25478
Hose - Lower .....		21182
		or ●26504
<b>John Deere 3-Cyl. 165 Diesel</b>		
1973-1968		
Belt - Fan & Alt. ....		7375
Hose - Upper .....		●25477
Hose - Lower .....		21182
		or ●26504
Hose - By Pass .....		28439
<b>1530</b>		
<b>John Deere 3-Cyl. 164 Diesel</b>		
1975-1974		
Belt - Fan & Alt.; W/Bosch Alt. ....	T23505	TR22461
Belt - Fan & Alt.; W/Motorola Alt. ....	T20334	TR22474
Hose - Lower .....		21182
Hose - By Pass .....		28439
<b>1650</b>		
<b>Yanmar 4-Cyl. 190 Diesel</b>		
1988-1984		
Belt - Fan & Alt. ....		▲9530HD
Hose - Upper .....		≧21660
		or ●25474
Hose - Lower .....		●25476
<b>2010</b>		
<b>John Deere 4-Cyl. 145</b>		
1965-1960		
Belt - Fan & Gen. ....	T626T	7480
Hose - Upper .....		≧21660
		or ●25476
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>John Deere 4-Cyl. 165 Diesel</b>		
1965-1960		
Belt - Fan & Gen. ....	T626T	7480
Hose - Upper .....		≧21660
		or ●25476
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>2020</b>		
<b>John Deere 4-Cyl. 180</b>		
1971-1965		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Upper .....		●25477

≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>2020 – Continued</b>		
<b>John Deere 4–Cyl. 180 – Continued</b>		
1971–1965 – Continued		
Hose - Lower .....		21182 or ●26603
<b>John Deere 4–Cyl. 203 Diesel</b>		
1971–1965		
Belt - Fan & Alt. ....	T20334T	TR22474
Hose - Upper .....		●25476
Hose - Lower .....		21182 or ●26502
<b>2030</b>		
<b>John Deere 4–Cyl. 219</b>		
1975–1972		
Belt - Fan & Alt. ....	T24473	TR22514
Hose - Upper .....		●25474
Hose - Lower .....		21182 or ●26502
Hose - By Pass .....		28439
<b>John Deere 4–Cyl. 219 Diesel</b>		
1975–1972		
Belt - Fan & Alt. ....	T20334	TR22474
Hose - Upper .....		●25477
Hose - By Pass .....		28439
<b>2040</b>		
<b>John Deere 3–Cyl. 164 Diesel</b>		
1979–1976		
Belt - Fan & Alt.; Ser. No. 349999 & Before .	T20334	TR22474
Belt - Fan & Alt.; Ser. No. 350000 & After ....	T31710	B51
Hose - Lower .....		21182
Hose - By Pass .....		28439
<b>John Deere 3–Cyl. 179 Diesel</b>		
1982–1980		
Belt - Fan & Alt.; Ser. No. 349999 & Before .	T20334	TR22474
Belt - Fan & Alt.; Ser. No. 350000 & After ....	T31710	B51
Hose - Lower .....		21182
Hose - By Pass .....		28439
<b>2150</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
1986–1983		
Belt - Fan & Alt. ....	R73784	TR22525
Hose - Lower .....		●26502
<b>2155</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
1992–1987		
Belt - Fan & Alt.; W/52 3/4" Belt O.C. ....	R73784	TR22525
Belt - Fan & Alt.; W/52 3/8" Belt O.C. ....	R97940	TR22525
Belt - Fan & Alt.; W/52" Belt O.C. ....	R97939	TR22517
<b>2240</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
1982–1976		
Belt - Fan & Alt.; Ser. No. 349999 & Before .	T20334	TR22474
Belt - Fan & Alt.; Ser. No. 350000 & After ....	T31710	B51
Hose - Lower .....		21182
Hose - By Pass .....		28439
<b>2255</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
1987–1983		
Belt - Fan & Alt. ....	R73784	TR22525
<b>2350</b>		
<b>John Deere 4–Cyl. 239 Diesel</b>		
1986–1983		
Belt - A.C. ....		▲9690HD
Belt - Fan & Alt. ....	R73784	TR22525

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>2350 – Continued</b>		
<b>John Deere 4–Cyl. 239 Diesel – Continued</b>		
1986–1983 – Continued		
Hose - Upper .....		●26501
Hose - Lower .....		●26508
<b>2355</b>		
<b>John Deere 4–Cyl. 239 Diesel</b>		
1992–1987		
Belt - A.C. ....	L59206	▲9700HD
Belt - Fan & Alt.; W/O Viscous Fan .....	R87154	TR22553
Belt - Fan & Alt.; W/Viscous Fan .....	R87153	TR22545
<b>2355N</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
1992–1987		
Belt - Fan & Alt.; W/52 3/4" Belt O.C. ....	R73784	TR22525
Belt - Fan & Alt.; W/52 3/8" Belt O.C. ....	R97940	TR22525
Belt - Fan & Alt.; W/52" Belt O.C. ....	R97939	TR22517
<b>2440</b>		
<b>John Deere 4–Cyl. 219 Diesel</b>		
1982–1976		
Belt - Fan & Alt. ....	T20334	TR22474
Hose - Upper; W/Horiz. Outlet .....		≧20450
Hose - Upper; W/Vert. Outlet .....		≧21794
Hose - Lower .....		21182
Hose - By Pass .....		28439
<b>2510</b>		
<b>John Deere 4–Cyl. 180</b>		
1968–1966		
Belt - Fan & Alt. ....	T24473	TR22514
Hose - Upper .....	R38481	21794
<b>John Deere 4–Cyl. 203 Diesel</b>		
1968–1966		
Belt - Fan & Alt. ....	T24473	TR22514
Hose - Upper .....		≧20065 or ●25473
Hose - Lower .....		●26502
Hose - By Pass .....		28439
<b>2520</b>		
<b>John Deere 4–Cyl. 203</b>		
1973–1969		
Belt - Fan & Alt. ....	T24473	TR22514
<b>John Deere 4–Cyl. 219 Diesel</b>		
1973–1969		
Belt - Fan & Alt. ....	T24473	TR22514
Hose - Upper .....		≧20065 or ●25473
Hose - Lower .....		●26502
Hose - By Pass .....		28439
<b>2550</b>		
<b>John Deere 4–Cyl. 239 Diesel</b>		
1986–1983		
Belt - A.C. ....	L41331	▲9690HD
Belt - Fan & Alt. ....	R73784	TR22525
<b>2555</b>		
<b>John Deere 4–Cyl. 239 Diesel</b>		
1992–1987		
Belt - A.C. ....	L59206	▲9700HD
Belt - Fan & Alt.; W/O Viscous Fan .....	R87154	TR22553
Belt - Fan & Alt.; W/Viscous Fan .....	R87153	TR22545
<b>2630</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
1975–1974		
Belt - Fan & Alt. ....	T24473	TR22514

≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>2630 – Continued</b>		
<b>John Deere 4-Cyl. 276 Diesel – Continued</b>		
1975–1974 – Continued		
Hose - Upper .....		20473 or ●25476
<b>2640</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
1983–1976		
Belt - Fan & Alt. ....	T24473	TR22514
Hose - Lower .....		21182
Hose - By Pass .....		20338
<b>2750</b>		
<b>John Deere 4-Cyl. 239 Diesel</b>		
1986–1983		
Belt - A.C.; W/67 1/4" Belt O.C. ....	L41330	▲9670HD
Belt - A.C.; W/69 1/4" Belt O.C. ....		▲9690HD
Belt - Fan & Alt. ....	R73784	TR22525
Hose - Lower .....		●26501
<b>2755</b>		
<b>John Deere 4-Cyl. 239 Diesel</b>		
1992–1987		
Belt - A.C. ....	L59206	▲9700HD
Belt - Fan & Alt.; W/O Viscous Fan .....	R87154	TR22553
Belt - Fan & Alt.; W/Viscous Fan .....	R87153	TR22545
Hose - Upper - Eng. To Pipe .....		20065
Hose - Upper - Pipe To Rad. ....		20065
<b>2840</b>		
<b>John Deere 6-Cyl. 329 Diesel</b>		
1979–1977		
Belt - Fan & Alt. ....	N150864	TR22545
Hose - Upper .....		✗20431
<b>2855N</b>		
<b>John Deere 4-Cyl. 239 Diesel</b>		
1992–1987		
Belt - Fan & Alt.; W/O Viscous Fan .....	R87154	TR22553
Belt - Fan & Alt.; W/Viscous Fan .....	R87153	TR22545
Hose - Upper - Eng. To Pipe .....		20065
Hose - Upper - Pipe To Rad. ....		20065
<b>2940</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1982–1980		
Belt - Fan & Alt. ....	R70446	TR22588
<b>2950</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1987–1983		
Belt - A.C. ....	L41330	▲9670HD
Belt - Fan & Alt. ....		TR22588
<b>2955</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1992–1987		
Belt - A.C. ....	L41330	▲9670HD
Belt - Fan & Alt. ....	R87152	TR22607
<b>3010</b>		
<b>John Deere 4-Cyl. 201</b>		
1963–1961		
Belt - Fan & Alt. ....	R41627	▲9560HD
Belt - Fan & Gen. ....	R26606R	▲9550HD
Hose - Upper .....		24232
		or ●26509
Hose - Lower .....		20590
		or ●26505

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>3010 – Continued</b>		
<b>John Deere 4-Cyl. 201 LPG</b>		
1963–1961		
Belt - Fan & Alt. ....	R41627	▲9560HD
Belt - Fan & Gen. ....	R26606R	▲9550HD
Hose - Upper .....		24232
		or ●26509
Hose - Lower .....		20590
		or ●26505
<b>John Deere 4-Cyl. 254 Diesel</b>		
1963–1961		
Belt - Fan & Alt. ....	R41628	▲9570HD
Belt - Fan & Gen. ....	R26607R	▲9555HD
Hose - Upper .....		24232
		or ●26509
Hose - Lower .....		20590
		or ●26505
<b>3020</b>		
<b>John Deere 4-Cyl. 227</b>		
1969–1964		
Belt - Fan & Alt. ....	R41627	▲9560HD
Belt - Fan & Gen. ....	R26606R	▲9550HD
Hose - Upper .....		24232
		or ●26509
Hose - Lower .....		20590
		or ●26505
<b>John Deere 4-Cyl. 227 LPG</b>		
1969–1964		
Belt - Fan & Alt. ....	R41627	▲9560HD
Belt - Fan & Gen. ....	R26606R	▲9550HD
Hose - Upper .....		24232
		or ●26509
Hose - Lower .....		20590
		or ●26505
<b>John Deere 4-Cyl. 241</b>		
1972–1970		
Belt - Fan & Alt. ....	R41627	▲9560HD
Belt - Fan & Gen. ....	R26606R	▲9550HD
Hose - Upper .....		24232
		or ●26509
Hose - Lower .....		20590
		or ●26505
<b>John Deere 4-Cyl. 241 LPG</b>		
1972–1970		
Belt - Fan & Alt. ....	R41627	▲9560HD
Belt - Fan & Gen. ....	R26606R	▲9550HD
Hose - Upper .....		24232
		or ●26509
Hose - Lower .....		20590
		or ●26505
<b>John Deere 4-Cyl. 270 Diesel</b>		
1972–1964		
Belt - Fan & Alt. ....	R41628	▲9570HD
Belt - Fan & Gen. ....	R26607R	▲9555HD
Hose - Upper .....		24232
		or ●26509
Hose - Lower .....		20590
		or ●26505
<b>3055</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1993–1991		
Belt - A.C. ....	L59206	▲9700HD
Belt - Fan & Alt. ....	R87152	TR22607
Hose - Upper .....		●26521
<b>3150</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1987–1985		
Belt - A.C. ....	L41330	▲9670HD
Belt - Fan & Alt. ....	R82174	TR22570

✗Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>3150 - Continued</b>		
<b>John Deere 6-Cyl. 359 Diesel - Continued</b>		
1987-1985 - Continued		
Hose - Upper .....		≈20744 or ●26534
<b>3155</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1991-1987		
Belt - A.C.; Ser. No. 663473 & Before .....	L41330	▲9670HD
Belt - A.C.; Ser. No. 663474 & After .....	L59206	▲9700HD
Belt - Fan & Alt.; W/Viscous Fan .....	R91407	TR22588
Hose - Upper .....		●26515
<b>3255</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1993-1992		
Belt - A.C. ....	L59206	▲9700HD
Belt - Fan & Alt. ....	R91407	TR22588
Hose - Upper .....		●26508
<b>4000</b>		
<b>John Deere 6-Cyl. 362</b>		
1972-1969		
Hose - Upper .....		24232 or ●26509
Hose - Lower .....		20590 or ●26505
<b>John Deere 6-Cyl. 404 Diesel</b>		
1972-1969		
Belt - A.C. ....	46098	▲9415HD
Belt - Fan & Alt.; W/A.C. ....	R46570	▲9600HD
Belt - Fan & Alt.; W/O A.C. ....		▲9570HD
Belt - Fan & Gen. ....	R26607R	▲9555HD
Hose - Upper .....		24232 or ●26509
Hose - Lower .....		20590 or ●26505
<b>4010</b>		
<b>John Deere 6-Cyl. 302</b>		
1963-1961		
Hose - Upper .....		24232 or ●26509
Hose - Lower .....		20590 or ●26505
<b>John Deere 6-Cyl. 302 LPG</b>		
1963-1961		
Hose - Upper .....		24232 or ●26509
Hose - Lower .....		20590 or ●26505
<b>John Deere 6-Cyl. 380 Diesel</b>		
1963-1961		
Hose - Upper .....		24232 or ●26509
Hose - Lower .....		20590 or ●26505
<b>4020</b>		
<b>John Deere 6-Cyl. 340</b>		
1972-1964		
Hose - Upper .....		24232 or ●26509
Hose - Lower .....		20590 or ●26505

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>4020 - Continued</b>		
<b>John Deere 6-Cyl. 340 LPG</b>		
1972-1964		
Hose - Upper .....		24232 or ●26509
Hose - Lower .....		20590 or ●26505
<b>John Deere 6-Cyl. 362</b>		
1972-1964		
Hose - Upper .....		24232 or ●26509
Hose - Lower .....		20590 or ●26505
<b>John Deere 6-Cyl. 362 LPG</b>		
1972-1964		
Hose - Upper .....		24232 or ●26509
Hose - Lower .....		20590 or ●26505
<b>John Deere 6-Cyl. 404 Diesel</b>		
1972-1964		
Belt - A.C. ....	46098	▲9415HD
Belt - Fan & Alt.; W/A.C. ....	R46570	▲9600HD
Belt - Fan & Alt.; W/O A.C. ....		▲9570HD
Belt - Fan & Gen. ....	R26607R	▲9555HD
Hose - Upper .....		24232 or ●26509
Hose - Lower .....		20590 or ●26505
<b>4030</b>		
<b>John Deere 6-Cyl. 303</b>		
1977-1973		
Belt - A.C. ....	R53258	▲9700HD
Belt - Fan & Alt. ....	R41628	▲9570HD
Hose - Lower .....		●26518
Hose - By Pass .....		28442
<b>John Deere 6-Cyl. 329 Diesel</b>		
1977-1973		
Belt - A.C.; Ser. No. 007171 & Before .....	R53258	▲9700HD
Belt - Fan & Alt.; W/57 1/4" Belt O.C. ....	R41628	▲9570HD
Belt - Fan & Alt.; W/59 1/4" Belt O.C. ....	R46113	▲9590HD
Hose - Upper .....		●26508
Hose - Lower .....		●26518
Hose - By Pass .....		28442
<b>4040</b>		
<b>John Deere 6-Cyl. 404 Diesel</b>		
1982-1978		
Belt - A.C. ....	R71603	▲9415HD
Belt - Fan & Alt. ....	R52603	▲9625HD
Hose - Upper .....		24232
<b>4050</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
1988-1987		
Belt - A.C. ....	B2893R	▲9405HD
Belt - Fan & Alt.; W/57 1/4" Belt O.C. ....	T26755	②▲9570HD
Belt - Fan & Alt.; W/59 1/4" Belt O.C. ....	H79235	②▲9590HD
Hose - Upper .....		21544
Hose - Lower .....		≈21135
<b>John Deere 6-Cyl. 466 Diesel</b>		
1986-1983		
Belt - A.C. ....	B2893R	▲9405HD
Belt - Fan & Alt.; W/57 1/4" Belt O.C. ....	T26755	②▲9570HD
Belt - Fan & Alt.; W/59 1/4" Belt O.C. ....	H79235	②▲9590HD
Hose - Upper .....		21544
Hose - Lower .....		≈21135

②Two Required ≈Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>4055</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1992-1989		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt.; W/66 3/8" Belt O.C. ....	RE29018	②▲9660HD
Hose - Upper .....		●26522
Hose - Lower .....		≧21135
<b>4110</b>		
<b>Yanmar 3-Cyl. 61 Diesel</b>		
2006-2002		
Belt - Fan; W/36 1/2" Belt O.C. ....	M800347	7360
Belt - Fan; W/36" Belt O.C. ....	M802674	7360
Belt - Fan; W/37" Belt O.C. ....	M811285	7370
<b>4115</b>		
<b>Yanmar 3-Cyl. 73 Diesel</b>		
2006-2002		
Belt - Fan & Alt. ....	RG60467	▲9380HD
<b>4200</b>		
<b>Yanmar 3-Cyl. 73 Diesel</b>		
2003-1998		
Belt - Fan .....		▲9390HD
<b>4230</b>		
<b>John Deere 6-Cyl. 362</b>		
1977-1973		
Belt - A.C. ....	R46098	▲9415HD
Belt - Fan & Alt. ....	R41681	▲9560HD
<b>John Deere 6-Cyl. 404 Diesel</b>		
1977-1973		
Belt - A.C. ....	R46098	▲9415HD
Belt - Fan & Alt.; W/62 3/4" Belt O.C. ....	R52603	▲9625HD
Belt - Fan & Alt.; W/64 1/4" Belt O.C. ....	R52604	▲9640HD
Hose - Upper .....		24232
		or ●26510
Hose - Lower .....		●26509
<b>4240</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1982-1978		
Belt - A.C.; W/41 3/4" Belt O.C. ....		▲9415HD
Belt - A.C.; W/42 3/4" Belt O.C. ....	R63900	▲9425HD
Belt - Fan & Alt. ....	AR74662	②▲9660HD
Hose - Lower; W/A.C. ....		21547
<b>4250</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1988-1983		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt. ....	RE29018	②▲9660HD
Hose - Upper .....		21544
Hose - Lower .....		≧21135
<b>4255</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1992-1989		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt.; W/66 3/8" Belt O.C. ....	RE29018	②▲9660HD
Hose - Upper .....		●26522
Hose - Lower .....		≧21135
<b>4300</b>		
<b>Yanmar 3-Cyl. 91 Diesel</b>		
2003-1998		
Belt - Fan .....		▲9412HD
<b>4310</b>		
<b>Yanmar 3-Cyl. 91 Diesel</b>		
2005-2002		
Belt - Fan & Alt.; W/40A. Alt. ....	LVU11661	▲9415HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>4320</b>		
<b>John Deere 6-Cyl. 404 Diesel</b>		
1972-1971		
Belt - Fan & Alt.; W/A.C. ....		②7612
Belt - Fan & Alt.; W/O A.C. ....	AR43219	②▲9600HD
Hose - Lower .....		●26524
<b>4400</b>		
<b>Yanmar 3-Cyl. 101 Diesel</b>		
2003-1998		
Belt - Fan .....		▲9420HD
<b>4410</b>		
<b>Yanmar 3-Cyl. 101 Diesel</b>		
2006-2002		
Belt - Fan & Alt.; W/40A. Alt. ....	LVU11661	▲9415HD
<b>4430</b>		
<b>John Deere 6-Cyl. 404 Diesel</b>		
1977-1973		
Belt - A.C. ....	R46098	▲9415HD
Belt - Fan & Alt.; W/A.C. ....	AR57266	②▲9630HD
Belt - Fan & Alt.; W/O A.C. ....	AR54592	②▲9625HD
<b>4440</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1982-1978		
Belt - A.C.; W/41 3/4" Belt O.C. ....		▲9415HD
Belt - A.C.; W/42 3/4" Belt O.C. ....	R63900	▲9425HD
Belt - Fan & Alt. ....	AR74662	②▲9660HD
Hose - Upper .....		21544
Hose - Lower; W/A.C. ....		21547
<b>4450</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1988-1983		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt. ....	RE29018	②▲9660HD
Hose - Upper .....		21544
Hose - Lower .....		≧21135
<b>4455</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1992-1989		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt.; W/66 3/8" Belt O.C. ....	RE29018	②▲9660HD
Hose - Upper .....		●26522
Hose - Lower .....		≧21135
<b>4500</b>		
<b>Yanmar 4-Cyl. 121 Diesel</b>		
2003-2001		
Belt - Fan; W/40A. Alt. ....	M802627	▲9412HD
Belt - Fan; W/55A. Alt. ....	LVU11661	▲9415HD
2000-1999		
Belt - Fan; W/40" Belt O.C. ....	M802627	▲9412HD
Belt - Fan; W/40A. Alt. ....	M802627	▲9412HD
Belt - Fan; W/41 1/2" Belt O.C. ....	M809527	▲9425HD
Belt - Fan; W/55A. Alt. ....	LVU11661	▲9415HD
1998		
Belt - Fan; W/40A. Alt. ....	M802627	▲9412HD
Belt - Fan; W/55A. Alt. ....	LVU11661	▲9415HD
<b>4510</b>		
<b>Yanmar 4-Cyl. 121 Diesel</b>		
2004-2003		
Belt - Fan & Alt.; W/40A. Alt. ....	LVU11661	▲9415HD
2002		
Belt - Fan & Alt.; W/40A. Alt. ....	LVU11661	▲9415HD
Belt - Fan & Alt.; W/Cab .....	R131435	▲K080855HD
Belt - Fan & Alt.; W/O Cab .....	R135438	K080635
		or ▲K080638HD
Tensioner Assy. - Fan & Alt. ....	RE52490	38507

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>4520</b>		
<b>John Deere 6-Cyl. 404 Diesel</b>		
1970-1969		
Belt - Fan & Alt.; W/O A.C. ....	AR43219	②▲9600HD
Hose - Upper .....		●26514
Hose - Lower .....		●26517
<b>4555</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1992-1989		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt.; W/66 3/8" Belt O.C. ....	RE29018	②▲9660HD
Hose - Upper .....		●26522
Hose - Lower .....		⊘<21135
<b>4560</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1994-1992		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt.; W/66 3/8" Belt O.C. ....	RE29018	②▲9660HD
Hose - Lower .....		21135
<b>4600</b>		
<b>Yanmar 4-Cyl. 121 Diesel</b>		
2003-1998		
Belt - Fan; W/40A. Alt. ....	M802627	▲9412HD
Belt - Fan; W/55A. Alt. ....	LVU11661	▲9415HD
<b>4610</b>		
<b>Yanmar 4-Cyl. 121 Diesel</b>		
2004-2002		
Belt - Fan & Alt.; W/40A. Alt. ....	LVU11661	▲9415HD
<b>4620</b>		
<b>John Deere 6-Cyl. 404 Diesel</b>		
1972-1971		
Belt - Fan & Alt. ....	AR51059	②▲9610HD
Hose - Lower .....		●26524
<b>4630</b>		
<b>John Deere 6-Cyl. 404 Diesel</b>		
1977-1973		
Belt - A.C. ....	R46098	▲9415HD
Belt - Fan & Alt.; W/A.C. ....	AR57266	②▲9630HD
Belt - Fan & Alt.; W/O A.C. ....	AR54592	②▲9625HD
<b>4640</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1982-1978		
Belt - A.C. ....	R71602	▲9425HD
Belt - Fan & Alt. ....	AR74662	▲9660HD
<b>4650</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1988-1983		
Belt - A.C. ....	R71602	▲9425HD
Belt - Fan & Alt. ....	AR74662	▲9660HD
Hose - Upper .....		21544
Hose - Lower; W/2 1/2" I.D. Hose .....		⊘<21135
Hose - Lower; W/3" I.D. Hose .....		⊘<21420
<b>4700</b>		
<b>Yanmar 4-Cyl. 134 Diesel</b>		
2003-2000		
Belt - Fan; W/40A. Alt. ....	M802627	▲9412HD
Belt - Fan; W/55A. Alt. ....	LVU11661	▲9415HD
<b>4710</b>		
<b>Yanmar 4-Cyl. 121 Diesel</b>		
2004-2002		
Belt - Fan & Alt.; W/40A. Alt. ....	LVU11661	▲9415HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>4755</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1991-1989		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt.; W/66 3/8" Belt O.C. ....	RE29018	②▲9660HD
<b>4760</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1994-1992		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt.; W/Dual Belts .....	RE29018	②▲9660HD
Belt - Fan & Alt.; W/Single Belt .....	RE41942	▲9660HD
Hose - Lower .....		24940
<b>4840</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1982-1978		
Belt - A.C. ....	R71602	▲9425HD
Belt - Fan & Alt. ....	AR74662	▲9660HD
<b>4850</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1988-1983		
Belt - A.C. ....	R71602	▲9425HD
Belt - Fan & Alt. ....	AR74662	▲9660HD
Hose - Upper .....		21544
Hose - Lower; W/2 1/2" I.D. Hose .....		⊘<21135
Hose - Lower; W/3" I.D. Hose .....		⊘<21420
<b>4955</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1991-1989		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt.; W/66 3/8" Belt O.C. ....	RE29018	②▲9660HD
<b>4960</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1994-1992		
Belt - A.C. ....		▲9405HD
Belt - Fan & Alt. ....	RE41942	②▲9660HD
Hose - Lower .....		21135
<b>5010</b>		
<b>John Deere 6-Cyl. 531 Diesel</b>		
1965-1963		
Belt - Fan & Alt./Gen. ....	AR41574	②7612
Hose - Upper .....		24232
Hose - Lower .....		●26526
Hose - By Pass - Front .....		24222
Hose - By Pass - Rear .....		⊘<21942
<b>5020</b>		
<b>John Deere 6-Cyl. 531 Diesel</b>		
1972-1966		
Belt - Fan & Alt.; W/A.C.; W/67 1/8" Belt O.C. ....	AR46970	②7665
Belt - Fan & Alt./Gen.; W/61 5/8" Belt O.C. ...	AR41574	②7612
Hose - Upper .....		24232
Hose - Lower .....		●26526
Hose - By Pass - Front .....		24222
Hose - By Pass - Rear .....		⊘<21942
<b>5065M</b>		
<b>John Deere 5-Cyl. 184 Diesel</b>		
2009		
Belt - Fan .....	R269264	K060623
Belt - Fan; W/O Cab .....	R270491	▲K060956HD
Tensioner Assy. ....	RE518097	38507

②Two Required ⊘<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>5065M – Continued</b>		
<b>John Deere 5-Cyl. 186 Diesel</b>		
2013-2011		
Belt - Fan; W/O Cab .....	R270491	♣K060956HD
2010		
Belt - Fan; W/O Cab .....	R270491	♣K060956HD
Tensioner Assy. ....	RE518097	38507
<b>5075M</b>		
<b>John Deere 3-Cyl. 179 Diesel</b>		
2017-2016		
Belt - Fan; W/O Cab .....	R270491	♣K060956HD
<b>John Deere 5-Cyl. 184 Diesel</b>		
2009		
Belt - Fan; W/O Cab .....	R270491	♣K060956HD
Tensioner Assy. ....	RE518097	38507
<b>John Deere 5-Cyl. 186 Diesel</b>		
2014-2011		
Belt - Fan; W/O Cab .....	R270491	♣K060956HD
2010		
Belt - Fan; W/O Cab .....	R270491	♣K060956HD
Tensioner Assy. ....	RE518097	38507
<b>5083E</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2013-2010		
Belt - Serpentine; Ser. No. 340000 & Before; W/O Cab .....	R133703	♣K080760HD
Belt - Serpentine; Ser. No. 340001 & After ..	SU303445	♣K080842HD
Tensioner Assy. ....	RE518097	38507
2009		
Belt - Fan; W/Cab .....	R133703	♣K080760HD
Belt - Fan; W/O Cab .....	R216071	♣K060594HD
Tensioner Assy. - Fan; W/Cab .....	RE518097	38507
Tensioner Assy. - Fan; W/O Cab .....	RE518097	38507
<b>5083EN</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2013-2010		
Belt - Serpentine; Ser. No. 370000 & Before; W/Cab .....	R216071	♣K060594HD
Belt - Serpentine; Ser. No. 370000 & Before; W/O Cab .....	R133703	♣K080760HD
Belt - Serpentine; Ser. No. 370001 & After; W/Cab .....	SU303445	♣K080842HD
Tensioner Assy. ....	RE518097	38507
2009		
Belt - Fan; W/Cab .....	R133703	♣K080760HD
Belt - Fan; W/O Cab .....	R216071	♣K060594HD
Tensioner Assy. - Fan; W/Cab .....	RE518097	38507
Tensioner Assy. - Fan; W/O Cab .....	RE518097	38507
<b>5085E</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2017-2016		
Tensioner Assy. ....	RE518097	38507
2015-2013		
Belt - Serpentine; W/Cab .....	SU23542	♣K080952HD
Tensioner Assy. ....	RE518097	38507
<b>5085M</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2014-2009		
Belt - Fan; W/Cab .....	R269265	♣K080855HD
Belt - Fan; W/O Cab .....	R269264	K060623
Tensioner Assy. ....	RE518097	38507

♣Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>5093E</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2013-2010		
Belt - Serpentine; Ser. No. 340000 & Before .....	R133703	♣K080760HD
Belt - Serpentine; Ser. No. 340001 & After ..	SU303445	♣K080842HD
Tensioner Assy. ....	RE518097	38507
2009		
Belt - Fan .....	R133703	♣K080760HD
Tensioner Assy. - Fan .....	RE518097	38507
<b>5093EN</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2013-2010		
Belt - Serpentine; Ser. No. 370000 & Before; W/Cab .....	R216071	♣K060594HD
Belt - Serpentine; Ser. No. 370000 & Before; W/O Cab .....	R133703	♣K080760HD
Belt - Serpentine; Ser. No. 370001 & After; W/Cab .....	SU303445	♣K080842HD
Tensioner Assy. ....	RE518097	38507
<b>5095M</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2011-2009		
Belt - Fan; W/Cab .....	R269265	♣K080855HD
Belt - Fan; W/O Cab .....	R269264	K060623
Tensioner Assy. ....	RE518097	38507
<b>5095MH</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2011-2010		
Belt - Fan; W/Cab .....	R269265	♣K080855HD
Belt - Fan; W/O Cab .....	R269264	K060623
Tensioner Assy. ....	RE518097	38507
2009		
Belt - Fan; W/O Cab .....	R270491	♣K060956HD
Tensioner Assy. ....	RE518097	38507
<b>5100E</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2015-2013		
Belt - Serpentine; W/Cab .....	SU23542	♣K080952HD
Tensioner Assy. ....	RE518097	38507
<b>5100M</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2014-2012		
Belt - Serpentine; W/Cab .....	SU23542	♣K080952HD
Tensioner Assy. ....	RE518097	38507
<b>5100MH; 5100ML</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2013-2012		
Belt - Serpentine; W/Cab .....	SU23542	♣K080952HD
Tensioner Assy. ....	RE518097	38507
<b>5101E</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2013-2010		
Belt - Serpentine; Ser. No. 340000 & Before .....	R133703	♣K080760HD
Belt - Serpentine; Ser. No. 340001 & After ..	SU303445	♣K080842HD
Tensioner Assy. ....	RE518097	38507
2009		
Belt - Fan .....	R133703	♣K080760HD
Tensioner Assy. - Fan .....	RE518097	38507
<b>5101EN</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
2013-2010		
Belt - Serpentine; Ser. No. 370000 & Before; W/Cab .....	R216071	♣K060594HD

Agricultural Equipment



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>5101EN – Continued</b>		
<b>John Deere 4–Cyl. 276 Diesel – Continued</b>		
2013–2010 – Continued		
Belt - Serpentine; Ser. No. 370000 & Before; W/O Cab .....	R133703	♣K080760HD
Belt - Serpentine; Ser. No. 370001 & After; W/Cab .....	SU303445	♣K080842HD
Tensioner Assy. ....	RE518097	38507
<b>5103</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
2008–2003		
Belt - Fan & Alt. ....	R73784	TR22525
<b>5105</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
2007–1999		
Belt - Fan .....	R73784	TR22525
<b>5105M</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
2012–2010		
Belt - Fan; W/Cab .....	R269265	♣K080855HD
Belt - Fan; W/O Cab .....	R269264	K060623
Tensioner Assy. ....	RE518097	38507
2009		
Belt - Fan; W/O Cab .....	R270491	♣K060956HD
Tensioner Assy. ....	RE518097	38507
<b>5105ML</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
2013–2010		
Belt - Fan; W/O Cab .....	R269264	K060623
Tensioner Assy. ....	RE518097	38507
<b>5115M</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
2014–2012		
Belt - Serpentine; W/Cab .....	SU23542	♣K080952HD
Tensioner Assy. ....	RE518097	38507
<b>5115ML</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
2013–2012		
Belt - Serpentine; W/Cab .....	SU23542	♣K080952HD
Tensioner Assy. ....	RE518097	38507
<b>5200</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
1997		
Belt - A.C. ....	R128502	♣9630HD
Belt - Fan & Alt. ....	R73784	TR22525
Hose - Upper .....	R105074B	21660
1996		
Belt - A.C. ....	R128502	♣9630HD
Belt - Fan & Alt.; W/Cab .....	R73784	TR22525
Hose - Upper .....	R126605	20065
1995–1992		
Belt - A.C. ....	R128502	♣9630HD
Belt - Fan & Alt. ....	R73784	TR22525
Hose - Upper .....	R126605	20065
<b>5203</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
2008–2003		
Belt - Alt. ....	R73784	TR22525
<b>5205</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
2007–1999		
Belt - Fan .....	R73784	TR22525

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>5210</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
2001–1998		
Belt - A.C. ....	R128502	♣9630HD
Belt - Fan .....	R73784	TR22525
Hose - Upper .....	R126605	20065
<b>5220</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
2004–2002		
Belt - A.C. ....	R128502	♣9630HD
Belt - Fan & Alt. ....	R73784	TR22525
Hose - Upper .....	R126605	20065
<b>5225</b>		
<b>John Deere 5–Cyl. 186 Diesel</b>		
2008–2005		
Belt - Fan & Alt. ....	R505810	♣K060923HD
Belt - Fan, Alt. & A.C. ....	R515218	♣K060950HD
<b>5300</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
1997–1992		
Belt - A.C. ....	R128502	♣9630HD
Belt - Fan & Alt. ....	R73784	TR22525
Hose - Upper .....	R126605	20065
<b>5303</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
2008–2003		
Belt - Alt. ....	R73784	TR22525
<b>5310</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
2001–1998		
Belt - A.C. ....	R128502	♣9630HD
Belt - Fan .....	R73784	TR22525
Hose - Upper .....	R126605	20065
<b>5320</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
2004–2001		
Belt - A.C. ....	R128502	♣9630HD
Belt - Fan & Alt. ....	R73784	TR22525
Hose - Upper .....	R126605	20065
<b>5325</b>		
<b>John Deere 5–Cyl. 186 Diesel</b>		
2008–2005		
Belt - Fan & Alt. ....	R505810	♣K060923HD
Belt - Fan, Alt. & A.C. ....	R515218	♣K060950HD
<b>5400</b>		
<b>John Deere 3–Cyl. 179 Diesel</b>		
1997		
Belt - A.C. ....	R128502	♣9630HD
Belt - Fan & Alt. ....	R73784	TR22525
Hose - Upper .....	R126605	20065
		or ●25473
1996–1992		
Belt - A.C. ....	R128502	♣9630HD
Belt - Fan & Alt. ....	R73784	TR22525
Hose - Upper .....		20065
		or ●25473

♣Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.	Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>			<b>JOHN DEERE - Continued</b>		
<b>5410</b>			<b>6100D - Continued</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>			<b>John Deere 4-Cyl. 276 Diesel - Continued</b>		
2001-1998			2009		
Belt - Fan, Alt. & A.C. ....	R135823	♣K080760HD	Belt - Fan; W/Cab .....	R270857	♣K080860HD
<b>5420</b>			<b>6105D</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>			<b>John Deere 4-Cyl. 276 Diesel</b>		
2004-2002			2014-2013		
Belt - Fan, Alt. & A.C. ....	R135823	♣K080760HD	Belt - Serpentine; W/Cab .....	SU23542	♣K080952HD
Tensioner Assy. ....	RE70536	38654	Tensioner Assy. ....	RE518097	38507
<b>5425</b>			<b>6110</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>			<b>John Deere 4045T Powertech Diesel</b>		
2008-2005			2001-1998		
Belt - Fan & Alt. ....	R216071	♣K060594HD	Belt - Fan & Alt. ....	L111601	♣K080760HD
Belt - Fan, Alt. & A.C. ....	R133703	♣K080760HD	Belt - Fan, Alt. & A.C. ....	L111601	♣K080968HD
Tensioner Assy. ....	RE518097	38507			
<b>5500</b>			<b>6115D</b>		
<b>John Deere 4-Cyl. 239 Diesel</b>			<b>John Deere 4-Cyl. 276 Diesel</b>		
1997-1996			2014-2010		
Belt - A.C. ....	R128502	♣9630HD	Belt - Serpentine; W/Cab .....	SU23542	♣K080952HD
Belt - Fan & Alt.; W/Cab .....	E75596	TR22553	Tensioner Assy. ....	RE518097	38507
Belt - Fan & Alt.; W/O Cab .....	N150864	TR22545	2009		
			Belt - Fan; W/Cab .....	R270857	♣K080860HD
			Tensioner Assy. - Fan .....	RE518097	38507
<b>5510</b>			<b>6120</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>			<b>John Deere 4-Cyl. 276 Diesel</b>		
2001-1998			2008-2002		
Belt - Fan, Alt. & A.C. ....	R135823	♣K080760HD	Belt - Fan & Alt. ....	L114489	♣K080760HD
			Belt - Fan, Alt. & A.C. ....	L111601	♣K080968HD
			Tensioner Assy. ....	AL156090	38661
<b>5520</b>			<b>6130D</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>			<b>John Deere 4-Cyl. 276 Diesel</b>		
2005-2000			2014-2010		
Belt - Fan, Alt. & A.C. ....	R135823	♣K080760HD	Belt - Serpentine; W/Cab .....	SU23542	♣K080952HD
Tensioner Assy. ....	RE70536	38654	Tensioner Assy. ....	RE518097	38507
<b>5525</b>			<b>6140D</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>			<b>John Deere 4-Cyl. 276 Diesel</b>		
2008-2005			2014-2010		
Belt - Fan & Alt. ....	R216071	♣K060594HD	Belt - Serpentine; W/Cab .....	SU23542	♣K080952HD
Belt - Fan, Alt. & A.C. ....	R133703	♣K080760HD	Tensioner Assy. ....	RE518097	38507
Tensioner Assy. ....	RE518097	38507	2009		
			Belt - Fan .....	R270857	♣K080860HD
			Tensioner Assy. - Fan .....	RE518097	38507
<b>5603</b>			<b>6140D</b>		
<b>John Deere 4045T Powertech Diesel</b>			<b>John Deere 4-Cyl. 276 Diesel</b>		
2008			2014-2010		
Belt - Fan .....	R133703	♣K080760HD	Belt - Serpentine; W/Cab .....	SU23542	♣K080952HD
Tensioner Assy. ....	RE518097	38507	Tensioner Assy. ....	RE518097	38507
<b>5625</b>			<b>6200</b>		
<b>John Deere 4045T Powertech Diesel</b>			<b>John Deere 4-Cyl. 239 Diesel</b>		
2008-2007			1997-1992		
Belt - Fan & Alt.; W/A.C. ....	R133703	♣K080760HD	Belt - Fan & Alt.; W/Hyd. Tensioner; Ser.		
Belt - Fan & Alt.; W/O A.C. ....	R216071	♣K060594HD	No. 125189 & Before .....	L111169	♣K060675HD
			Belt - Fan & Alt.; W/Hyd. Tensioner; Ser.		
			No. 125190 & After .....	L111685	♣K080685HD
			Belt - Fan & Alt.; W/Mech. Tensioner .....	L111169	♣K060675HD
			Belt - Fan, Alt. & A.C.; W/Hyd. Tensioner .....	L111170	♣K080876HD
			Belt - Fan, Alt. & A.C.; W/Mech. Tensioner .....	L110605	♣K080868HD
			Tensioner Assy.; W/Mech. Tensioner .....	AL110621	38660
<b>6030</b>			<b>6210</b>		
<b>John Deere 6-Cyl. 531 Diesel</b>			<b>John Deere 4045T Powertech Diesel</b>		
1977-1972			2001-1998		
Belt - A.C. ....	R49422	♣9430HD	Belt - Fan & Alt. ....	L111601	♣K080760HD
Belt - Fan; W/61 5/8" Belt O.C. ....	AR56638	②7612	Belt - Fan, Alt. & A.C. ....	L111601	♣K080968HD
Belt - Fan; W/67 1/8" Belt O.C. ....	AR46970	②7665			
Belt - Fan & Alt. ....	AR53099	②♣9650HD			
Hose - Upper .....		●26510			
Hose - Lower .....		●26526			
Hose - Lower - Eng. To Pipe; Ser. No. 288433 & After .....		≧21400			
Hose - By Pass .....		≧20267			
<b>6100D</b>			<b>6215</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>			<b>John Deere 4045T Powertech Diesel</b>		
2012-2010			2008-2003		
Belt - Serpentine; W/Cab .....	R270857	♣K080860HD	Belt - Fan & Alt. ....	114489	♣K080760HD
Tensioner Assy. ....	RE518097	38507			

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6215 – Continued</b>		
<b>John Deere 4045T Powertech Diesel – Continued</b>		
2008–2003 – Continued		
Belt - Fan, Alt. & A.C. ....	L111601	▲K080968HD
Tensioner Assy. ....	AL156090	38661
<b>6220</b>		
<b>John Deere 4045T Powertech Diesel</b>		
2008–2002		
Belt - Fan & Alt. ....	L114489	▲K080760HD
Belt - Fan, Alt. & A.C. ....	L111601	▲K080968HD
Tensioner Assy. ....	AL156090	38661
<b>6230</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
2013–2010		
Belt - Serpentine; W/A.C. ....	L111600	▲K080968HD
Belt - Serpentine; W/O A.C. ....	L114488	▲K080751HD
Tensioner Assy. ....	AL156090	38661
2009		
Belt - Fan & Alt. ....	L114488	▲K080751HD
Belt - Fan, Alt. & A.C. ....	L155538	▲K080968HD
Tensioner Assy. - Fan ....	AL156090	38661
<b>6300</b>		
<b>John Deere 4–Cyl. 239 Diesel</b>		
1997–1992		
Belt - Fan & Alt.; W/Hyd. Tensioner; Ser. No. 125189 & Before ....	L111169	▲K060675HD
Belt - Fan & Alt.; W/Hyd. Tensioner; Ser. No. 125190 & After ....	L111685	▲K080685HD
Belt - Fan & Alt.; W/Mech. Tensioner ....	L111169	▲K060675HD
Belt - Fan, Alt. & A.C.; W/Hyd. Tensioner; Ser. No. 106163 & Before ....	L111170	▲K080876HD
Belt - Fan, Alt. & A.C.; W/Hyd. Tensioner; Ser. No. 106164 & After ....	L110606	▲K080878HD
Belt - Fan, Alt. & A.C.; W/Mech. Tensioner ..	L110605	▲K080868HD
Tensioner Assy.; W/Mech. Tensioner ....	AL110621	38660
Hose - Upper .....	21115	or ●26531
<b>6310</b>		
<b>John Deere 4045T Powertech Diesel</b>		
2001–1998		
Belt - Fan & Alt. ....		▲K080760HD
Belt - Fan, Alt. & A.C. ....	L111600	▲K080968HD
<b>6320</b>		
<b>John Deere 4045T Powertech Diesel</b>		
2008–2002		
Belt - Fan & Alt. ....	L114489	▲K080760HD
Belt - Fan, Alt. & A.C. ....	L111601	▲K080968HD
Tensioner Assy. ....	AL156090	38661
Alt. Decoupler Pulley Tool .....		91024
<b>6330</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
2013–2010		
Belt - Serpentine; W/A.C. ....	L155538	▲K080968HD
Belt - Serpentine; W/O A.C. ....	L153280	▲K080751HD
Tensioner Assy. ....	AL156090	38661
2009		
Belt - Fan & Alt. ....	L153280	▲K080751HD
Belt - Fan, Alt. & A.C. ....	L155538	▲K080968HD
Tensioner Assy. - Fan ....	AL156090	38661
<b>6400</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
1997–1992		
Belt - Fan & Alt.; W/Hyd. Tensioner; Ser. No. 125189 & Before ....	L111169	▲K060675HD
Belt - Fan & Alt.; W/Hyd. Tensioner; Ser. No. 125190 & After ....	L111685	▲K080685HD
Belt - Fan & Alt.; W/Mech. Tensioner ....	L111169	▲K060675HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6400 – Continued</b>		
<b>John Deere 4–Cyl. 276 Diesel – Continued</b>		
1997–1992 – Continued		
Belt - Fan, Alt. & A.C.; W/Hyd. Tensioner ....	L111170	▲K080876HD
Belt - Fan, Alt. & A.C.; W/Mech. Tensioner ..	L110605	▲K080868HD
Tensioner Assy.; W/Mech. Tensioner .....	AL110621	38660
<b>6403</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
2008–2002		
Belt - Fan & Alt. ....	R502599	K080644
Belt - Fan, Alt. & A.C. ....	R500381	▲K080903HD
<b>6405 Advantage</b>		
<b>John Deere 4045T Powertech Diesel</b>		
2002		
Belt - Fan & Alt. ....	L114489	▲K080760HD
Belt - Fan, Alt. & A.C. ....	L111600	▲K080968HD
2001–1997		
Belt - Fan ....	8K1930	▲K080760HD
Belt - Fan & Alt. ....	L114489	▲K080760HD
Belt - Fan, Alt. & A.C. ....	L111600	▲K080968HD
<b>6410</b>		
<b>John Deere 4045T Powertech Diesel</b>		
2001		
Belt - Fan & Alt. ....	L114489	▲K080760HD
Belt - Fan, Alt. & A.C. ....	L111601	▲K080968HD
2000–1998		
Belt - Fan & Alt. ....		▲K080760HD
Belt - Fan, Alt. & A.C. ....	L111600	▲K080968HD
<b>6415</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
2008–2005		
Belt - Fan & Alt. ....	L114489	▲K080760HD
Belt - Fan, Alt. & A.C. ....	L111601	▲K080968HD
Tensioner Assy. ....	AL156090	38661
2004–2003		
Belt - Fan & Alt. ....	114489	▲K080760HD
Belt - Fan, Alt. & A.C. ....	L111601	▲K080968HD
Tensioner Assy. ....	AL156090	38661
<b>6420</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
2008–2002		
Belt - Fan & Alt. ....	L114489	▲K080760HD
Belt - Fan, Alt. & A.C. ....	L111601	▲K080968HD
Tensioner Assy. ....	AL156090	38661
Alt. Decoupler Pulley Tool .....		91024
<b>6430</b>		
<b>John Deere 4–Cyl. 276 Diesel</b>		
2013–2010		
Belt - Serpentine; W/A.C. ....	L155538	▲K080968HD
Belt - Serpentine; W/O A.C. ....	L153280	▲K080751HD
Tensioner Assy. ....	AL156090	38661
2009		
Belt - Fan & Alt. ....	L153280	▲K080751HD
Belt - Fan, Alt. & A.C. ....	L155538	▲K080968HD
Tensioner Assy. - Fan ....	AL156090	38661
2008–2007		
Belt - Fan & Alt. ....	L153280	▲K080751HD
Belt - Fan, Alt. & A.C. ....	L155538	▲K080968HD
Tensioner Assy. ....	AL156090	38661
<b>6500L</b>		
<b>John Deere 4–Cyl. 239 Diesel</b>		
1995		
Belt - Fan & Alt.; Ser. No. 159438 & Before; W/Hyd. Tensioner .....	L110600	▲K080670HD
Belt - Fan & Alt.; Ser. No. 159439 & After; W/Mech. Tensioner .....	L110599	▲K060660HD

⊗Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>6500L - Continued</b>		
<b>John Deere 4-Cyl. 239 Diesel - Continued</b>		
<b>1995 - Continued</b>		
Tensioner Assy.; W/Mech. Tensioner .....	AL110621	38660
<b>John Deere 4-Cyl. 276 Diesel</b>		
<b>1997</b>		
Belt - Fan & Alt.; Ser. No. 159438 & Before; W/Hyd. Tensioner .....	L110600	♣K080670HD
Belt - Fan & Alt.; Ser. No. 159439 & After; W/Mech. Tensioner .....	L110599	♣K080660HD
Tensioner Assy.; W/Mech. Tensioner .....	AL110621	38660
<b>1996</b>		
Belt - Fan & Alt.; Ser. No. 159438 & Before; W/Hyd. Tensioner .....	L110600	♣K080670HD
Belt - Fan & Alt.; Ser. No. 159439 & After; W/Mech. Tensioner .....	L110599	♣K060660HD
Tensioner Assy.; W/Mech. Tensioner .....	AL110621	38660
<b>1994</b>		
Belt - Fan & Alt.; Ser. No. 159438 & Before; W/Hyd. Tensioner .....	L110600	♣K080670HD
Belt - Fan & Alt.; Ser. No. 159439 & After; W/Mech. Tensioner .....	L110599	♣K060660HD
Tensioner Assy.; W/Mech. Tensioner .....	AL110621	38660
<b>6510</b>		
<b>John Deere 4045T Powertech Diesel</b>		
<b>2001-1998</b>		
Belt - Fan & Alt. ....	L114489	♣K080760HD
Belt - Fan, Alt. & A.C. ....	L111600	♣K080968HD
<b>6520L</b>		
<b>John Deere 4045T Powertech Diesel</b>		
<b>2008-2002</b>		
Belt - Fan & Alt. ....	L111601	♣K080968HD
Belt - Fan, Alt. & A.C. ....	L114489	♣K080760HD
Tensioner Assy. ....	AL156090	38661
<b>6603</b>		
<b>John Deere 6-Cyl. 414 Diesel</b>		
<b>2008-2002</b>		
Belt - Fan & A.C. ....	R505186	♣K080657HD
Belt - Fan, Alt. & A.C. ....	R135194	♣K080926HD
<b>6605 Advantage</b>		
<b>John Deere 6068T Powertech Diesel</b>		
<b>2002</b>		
Belt - Fan & Alt. ....	L114488	♣K080751HD
Belt - Fan, Alt. & A.C. ....	L111600	♣K080968HD
<b>2001-1997</b>		
Belt - Fan ....	L114488	♣K080751HD
Belt - Fan & Alt. ....	L114488	♣K080751HD
Belt - Fan, Alt. & A.C. ....	L111600	♣K080968HD
<b>6615; 6715</b>		
<b>John Deere 6-Cyl. 414 Diesel</b>		
<b>2008-2002</b>		
Belt - Fan & A.C. ....	L155538	♣K080968HD
Belt - Fan & Alt. ....	L114488	♣K080751HD
Belt - Fan, Alt. & A.C. ....	L111601	♣K080968HD
Tensioner Assy. ....	AL156090	38661
<b>7020</b>		
<b>John Deere 6-Cyl. 404 Diesel</b>		
<b>1975-1971</b>		
Belt - A.C. ....	R46098	♣9415HD
Belt - Fan & Alt.; Ser. No. 335846 & After; W/59 1/4" Belt O.C. ②	♣9590HD	
Belt - Fan & Alt.; Ser. No. 335846 & After; W/63 1/4" Belt O.C. ....	AR57266	②♣9630HD
Belt - Fan & Alt.; W/A.C.; Ser. No. 335845 & Before ....	AR56638	②7612
Belt - Fan & Alt.; W/O A.C.; Ser. No. 335845 & Before ....	AR51059	②♣9610HD
Hose - Upper - Pipe To Rad.; Ser. No. 002699 & Before .....	24432	
Hose - Lower .....	♣20748	

②Two Required ③Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>7130</b>		
<b>John Deere 4-Cyl. 276 Diesel</b>		
<b>2013-2010</b>		
Belt - Serpentine; W/A.C. ....	L111601	♣K080968HD
Belt - Serpentine; W/O A.C. ....	L114488	♣K080751HD
Tensioner Assy. ....	AL156090	38661
<b>John Deere 6-Cyl. 414 Diesel</b>		
<b>2013-2010</b>		
Belt - Serpentine; W/A.C. ....	L111601	♣K080968HD
Belt - Serpentine; W/O A.C. ....	L114488	♣K080751HD
Tensioner Assy. ....	AL156090	38661
<b>2009-2008</b>		
Belt - Fan & Alt. ....	L114488	♣K080751HD
Belt - Fan, Alt. & A.C. ....	L111601	♣K080968HD
Tensioner Assy. - Serpentine .....	AL156090	38661
Alt. Decoupler Pulley Tool .....		91024
<b>7130 Premium</b>		
<b>John Deere 6-Cyl. 414 Diesel</b>		
<b>2009-2008</b>		
Belt - Fan, Alt. & A.C. ....	L111601	♣K080968HD
Tensioner Assy. - Serpentine .....	AL156090	38661
Alt. Decoupler Pulley Tool .....		91024
<b>7200</b>		
<b>John Deere 6-Cyl. 359 Diesel</b>		
<b>1996-1993</b>		
Belt - Fan & Alt.; W/Cab .....	R118317	♣K080710HD
Belt - Fan & Alt.; W/O Cab .....	R95917	K080644
Belt - Fan, Alt. & A.C. ....	R115614	♣K080903HD
Hose - Upper .....	R113176A	●26511
<b>7200R</b>		
<b>John Deere 6-Cyl. 414 Diesel</b>		
<b>2014-2011</b>		
Belt - Serpentine .....	R310956	♣K080893HD
<b>7210</b>		
<b>John Deere 6-Cyl. 414 Diesel</b>		
<b>2002-1996</b>		
Belt - Fan & Alt.; W/Cab .....	R131435	♣K080855HD
Belt - Fan & Alt.; W/O Cab .....	R135438	K080635
Tensioner Assy. - Fan & Alt. ....	RE52490	or K080638HD 38507
<b>7215R</b>		
<b>John Deere 6-Cyl. 414 Diesel</b>		
<b>2014-2011</b>		
Belt - Serpentine .....	R310956	♣K080893HD
<b>7220</b>		
<b>John Deere 6-Cyl. 414 Diesel</b>		
<b>2008-2003</b>		
Belt - Fan & Alt. ....	L114488	♣K080751HD
Belt - Fan, Alt. & A.C. ....	L111601	♣K080968HD
Tensioner Assy. ....	AL156090	38661
<b>7230</b>		
<b>John Deere 6-Cyl. 414 Diesel</b>		
<b>2013-2011</b>		
Belt - Serpentine; W/A.C. ....	L111600	♣K080968HD
Belt - Serpentine; W/O A.C. ....	L114488	♣K080751HD
Tensioner Assy. - Serpentine .....	AL156090	38661
<b>2010-2008</b>		
Belt - Serpentine; W/A.C. ....	L111600	♣K080968HD
Belt - Fan & Alt. ....	L114488	♣K080751HD
Tensioner Assy. - Serpentine .....	AL156090	38661
<b>7230 Premium</b>		
<b>John Deere 6-Cyl. 414 Diesel</b>		
<b>2011</b>		
Belt - Serpentine .....	L111600	♣K080968HD

Agricultural Equipment





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>7230 Premium – Continued</b>		
<b>John Deere 6–Cyl. 414 Diesel – Continued</b>		
<b>2011 – Continued</b>		
Tensioner Assy. - Serpentine .....	AL156090	38661
<b>2010–2008</b>		
Belt - Serpentine .....	L111600	♣K080968HD
Tensioner Assy. - Serpentine .....	AL156090	38661
Alt. Decoupler Pulley Tool .....		91024
<b>7260R; 7280R</b>		
<b>John Deere 6–Cyl. 548 Diesel</b>		
<b>2013–2011</b>		
Belt - Serpentine .....	R310958	♣K080872HD
<b>7320</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2008–2003</b>		
Belt - Fan & Alt. ....	L114488	♣K080751HD
Belt - Fan, Alt. & A.C. ....	L111600	♣K080968HD
Tensioner Assy. ....	AL156090	38661
<b>7330</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2013–2010</b>		
Belt - Serpentine; W/A.C. ....	L155538	♣K080968HD
Belt - Serpentine; W/O A.C. ....	L153280	♣K080751HD
Tensioner Assy. - Serpentine .....	AL156090	38661
<b>2009–2008</b>		
Belt - Serpentine; W/A.C. ....	L155538	♣K080968HD
Belt - Serpentine; W/O A.C. ....	L153280	♣K080751HD
Tensioner Assy. - Serpentine .....	AL156090	38661
Alt. Decoupler Pulley Tool .....		91024
<b>7330 Premium</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2012</b>		
Belt - Serpentine; W/A.C. ....	L169273	♣K080897HD
Belt - Serpentine; W/O A.C. ....	L155538	♣K080968HD
Tensioner Assy. - Serpentine .....	AL156090	38661
Alt. Decoupler Pulley Tool .....		91024
<b>2010–2008</b>		
Belt - Serpentine; W/A.C. ....	L169273	♣K080897HD
Belt - Serpentine; W/O A.C. ....	L155538	♣K080968HD
Tensioner Assy. - Serpentine .....	AL156090	38661
Alt. Decoupler Pulley Tool .....		91024
<b>7400 Tractor</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>1996–1994</b>		
Belt - Fan & Alt. ....	R118317	♣K080710HD
Belt - Fan, Alt. & A.C. ....	R115614	♣K080903HD
Tensioner Assy. ....	RE52490	38507
Hose - Upper .....	R113176A	●26511
<b>7405 Advantage</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2002–1998</b>		
Belt - Fan & Alt. ....	R123453	K080635
		or K080638HD
<b>7410</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2002–1997</b>		
Belt - Fan & Alt.; W/Cab .....	R131435	♣K080855HD
Belt - Fan & Alt.; W/O Cab .....	R135438	K080635
		or K080638HD
Tensioner Assy. - Fan & Alt. ....	RE52490	38507
<b>7420</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2008–2003</b>		
Belt - Fan & Alt. ....	L153280	♣K080751HD
Belt - Fan, Alt. & A.C. ....	L153285	♣K080968HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>7420 – Continued</b>		
<b>John Deere 6–Cyl. 414 Diesel – Continued</b>		
<b>2008–2003 – Continued</b>		
Tensioner Assy. ....	AL156090	38661
<b>7430 Premium</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2012–2010</b>		
Belt - Serpentine .....	L169273	♣K080897HD
Tensioner Assy. - Serpentine .....	AL156090	38661
<b>2009–2008</b>		
Belt - Serpentine .....	L169273	♣K080897HD
Tensioner Assy. - Serpentine .....	AL156090	38661
Alt. Decoupler Pulley Tool .....		91024
<b>7510</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2002–1999</b>		
Belt - Fan & Alt.; W/Cab .....	R131435	♣K080855HD
Belt - Fan & Alt.; W/O Cab .....	R135438	K080635
		or K080638HD
Tensioner Assy. - Fan & Alt. ....	RE52490	38507
<b>7520</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2008–2003</b>		
Belt - Fan & Alt. ....	L153280	♣K080751HD
Belt - Fan, Alt. & A.C. ....	L153285	♣K080968HD
Tensioner Assy. ....	AL156090	38661
<b>John Deere 6–Cyl. 531 Diesel</b>		
<b>1975–1972</b>		
Belt - A.C. ....	R49422	♣9430HD
Belt - Fan; W/61 5/8" Belt O.C. ....	AR56638	②7612
Belt - Fan; W/67 1/8" Belt O.C. ....	AR46970	②7665
Belt - Fan & Alt. ....	AR53099	②♣9650HD
<b>7530</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2011</b>		
Belt - Serpentine .....	L169273	♣K080897HD
Tensioner Assy. - Serpentine .....	AL156090	38661
<b>7530 Premium</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2012–2010</b>		
Belt - Serpentine .....	L169273	♣K080897HD
Tensioner Assy. - Serpentine .....	AL156090	38661
<b>7600</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>1996–1992</b>		
Belt - Fan & Alt.; W/Air Brake Compr. ....	R115936	♣K080897HD
Belt - Fan & Alt.; W/O Air Brake Compr. ....	R95917	K080644
Belt - Fan, Alt. & A.C.; W/Air Brake Compr. ....	R115935	♣K081020HD
Belt - Fan, Alt. & A.C.; W/O Air Brake Compr. ....	R95924	♣K080903HD
Tensioner Assy. - Fan, Alt. & A.C. ....	RE68715	38507
Tensioner Pulley - Fan, Alt. & A.C. ....	RE68715	36091
<b>7610</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2002–1996</b>		
Belt - Fan & Alt.; W/O A.C. ....	R123460	♣K080660HD
Belt - Fan, Alt. & A.C. ....	R115614	♣K080903HD
Tensioner Assy. - Fan, Alt. & A.C. ....	RE52490	38507
<b>7630</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
<b>2011–2009</b>		
Belt - Fan; W/O Viscous Fan Clutch .....	R267275	♣K081000HD
Belt - Fan; W/Viscous Fan Clutch .....	R245222	♣K080986HD
Tensioner Assy. - Fan; W/O Viscous Fan ....	RE232242	38507
Tensioner Assy. - Fan; W/Viscous Fan .....	RE232242	38507

②Two Required ●Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>7630 – Continued</b>		
<b>John Deere 6–Cyl. 414 Diesel – Continued</b>		
2008–2007		
Belt - Fan; W/O Viscous Fan Clutch .....	R267275	▲K081000HD
Belt - Fan; W/Viscous Fan Clutch .....	R245222	▲K080986HD
Tensioner Assy. ....	RE232242	38507
<b>7700</b>		
<b>John Deere 6–Cyl. 466 Diesel</b>		
1996–1993		
Belt - Fan & Alt. ....	R106122	▲K080653HD
Belt - Fan, Alt. & A.C. ....	R106120	▲K080751HD
Tensioner Assy. - Fan, Alt. & A.C. ....	RE68715	38507
Tensioner Pulley - Fan, Alt. & A.C. ....	RE68715	36091
<b>7710</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
2003–1996		
Belt - Fan & Alt.; W/Cab .....	R133518	▲K080790HD
Belt - Fan & Alt.; W/O Cab .....	R123459	▲K080660HD
Tensioner Assy. - Fan & Alt. ....	RE68715	38507
Tensioner Pulley - Fan, Alt. & A.C. ....	RE68715	36091
<b>7720 Tractor</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
2006–2004		
Belt - Fan, Alt. & A.C. ....	R202628	▲K080986HD
Hose - Upper - Eng. To Pipe .....	R43582	●26514
<b>7730</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
2011–2009		
Belt - Fan; W/O Viscous Fan Clutch .....	R267275	▲K081000HD
Belt - Fan; W/Viscous Fan Clutch .....	R245222	▲K080986HD
Tensioner Assy. - Fan; W/O Viscous Fan ....	RE232242	38507
Tensioner Assy. - Fan; W/Viscous Fan .....	RE232242	38507
2008–2007		
Belt - Fan; W/O Viscous Fan Clutch .....	R267275	▲K081000HD
Belt - Fan; W/Viscous Fan Clutch .....	R245222	▲K080986HD
Tensioner Assy. ....	RE232242	38507
<b>7800</b>		
<b>John Deere 6–Cyl. 466 Diesel</b>		
1996–1992		
Belt - Fan & Alt. ....	R106122	▲K080653HD
Belt - Fan, Alt. & A.C. ....	R106120	▲K080751HD
Tensioner Assy. - Fan, Alt. & A.C. ....	RE68715	38507
Tensioner Pulley - Fan, Alt. & A.C. ....	RE68715	36091
<b>7810</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
2003–1998		
Belt - Fan .....	R128210	▲K081065HD
1997		
Belt - Fan; W/Cab .....	R174754	▲K080790HD
Belt - Fan; W/Trailer Brakes .....	R128210	▲K081065HD
Belt - Fan & Alt.; W/O Cab .....	R123459	▲K080660HD
1996		
Belt - Fan .....	R128210	▲K081065HD
<b>7820</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
2006–2004		
Belt - Fan, Alt. & A.C. ....	R181918	▲K081074HD
Hose - Upper - Eng. To Pipe .....	R43582	●26514
<b>7830</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
2011–2009		
Belt - Fan; W/O Viscous Fan .....	R267275	▲K081000HD
Belt - Fan; W/Viscous Fan .....	R245223	K080981
Tensioner Assy. - Fan; W/O Viscous Fan ....	RE232242	38507
Tensioner Assy. - Fan; W/Viscous Fan .....	RE232242	38507

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>7830 – Continued</b>		
<b>John Deere 6–Cyl. 414 Diesel – Continued</b>		
2008–2007		
Belt - Fan; W/O Viscous Fan Clutch .....	R267275	▲K081000HD
Belt - Fan; W/Viscous Fan Clutch .....	R245223	K080981
Tensioner Assy. ....	RE232242	38507
<b>7920</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
2006–2004		
Belt - Fan, Alt. & A.C. ....	R202629	▲K081065HD
Hose - Upper - Eng. To Pipe .....	R43582	●26514
<b>7930</b>		
<b>John Deere 6–Cyl. 414 Diesel</b>		
2011–2009		
Belt - Fan; W/O Viscous Fan .....	R265241	▲K080994HD
Tensioner Assy. - Fan; W/O Viscous Fan ....	RE232242	38507
Tensioner Assy. - Fan; W/Viscous Fan .....	RE232242	38507
2008–2007		
Tensioner Assy. ....	RE232242	38507
<b>8010</b>		
<b>GM 6–Cyl. 426 Diesel</b>		
1961–1960		
Belt - Fan .....	AR29285R	②▲9420HD
Belt - Gen. ....	R29474R	▲9360HD
Hose - Upper .....		③<20420
		or ●26508
Hose - Lower .....		20744
<b>8020</b>		
<b>GM 6–Cyl. 426 Diesel</b>		
1964–1961		
Belt - Fan .....	AR29285R	②▲9420HD
Belt - Gen. ....	R29474R	▲9360HD
Hose - Upper .....		③<20420
		or ●26508
Hose - Lower .....		20744
<b>8100</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
1999–1997		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R124786	▲K080760HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R124785	▲K080496HD
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>John Deere 6–Cyl. 466 Diesel</b>		
1996–1995		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R124786	▲K080760HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R124785	▲K080496HD
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8100T</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
1999–1997		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R124786	▲K080760HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R124785	▲K080496HD
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8110</b>		
<b>John Deere 6–Cyl. 8.1 L Diesel</b>		
2001–1999		
Belt - Air Brake Compr. ....	R157688	▲K080760HD
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621

②Two Required ③<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>8110T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2001-1999		
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8120</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2005		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr.; Ser. No. 023919 & After .....	R228118	▲K080710HD
Belt - Fan .....	R164820	▲K080468HD
Tensioner Pulley - Alt. & A.C. ....	RE184034	36091
2004		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Belt - Fan .....	R164820	▲K080468HD
Tensioner Pulley - Alt. & A.C. ....	RE184034	36091
2003-2002		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Belt - Fan .....	R164820	▲K080468HD
Tensioner Pulley .....	RE184034	36091
<b>8120T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2005-2002		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Belt - Fan .....	R164820	▲K080468HD
<b>8130</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2009-2008		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	▲K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	▲K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
<b>8200</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
1999-1995		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R124786	▲K080760HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R124785	▲K080496HD
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8200T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
1999-1997		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R124786	▲K080760HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R124785	▲K080496HD
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8210</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2001-2000		
Belt - Air Brake Compr. ....	R157688	▲K080760HD
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8210T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2001-2000		
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8220</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2005-2004		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>8220 - Continued</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel - Continued</b>		
2005-2004 - Continued		
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Tensioner Pulley - Alt. & A.C. ....	RE184034	36091
2003-2002		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Tensioner Pulley .....	RE184034	36091
<b>8220T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2005-2002		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Belt - Fan .....	R164820	▲K080468HD
<b>8225R</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2010		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	▲K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	▲K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
<b>8230; 8230T</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2009-2008		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	▲K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	▲K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
2007-2006		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R210808	▲K080830HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R211183	▲K080510HD
Tensioner Assy. - Alt. & A.C. ....	RE243199	38613
Idler Pulley; W/Air Brakes .....	RE232483	38076
<b>8235R</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014-2011		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	▲K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	▲K080510HD
Idler Pulley .....	RE232483	38076
<b>8245R</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014		
Tensioner Assy.; W/O Air Brake Compr. ....	RE232242	38507
Idler Pulley .....	RE232483	38076
2010		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	▲K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	▲K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
<b>8260R</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014-2011		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	▲K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	▲K080510HD
Idler Pulley .....	RE232483	38076
<b>8270R</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014		
Tensioner Assy.; W/O Air Brake Compr. ....	RE232242	38507
Idler Pulley .....	RE232483	38076
2010		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	▲K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	▲K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024

▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>8285R</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014-2011		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	♣K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	♣K080510HD
Idler Pulley .....	RE232483	38076
<b>8295R</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014		
Tensioner Assy.; W/O Air Brake Compr. ....	RE232242	38507
Idler Pulley .....	RE232483	38076
2010		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	♣K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	♣K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
<b>8295RT</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2010		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	♣K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	♣K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
<b>8300</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
1999-1997		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R124786	♣K080760HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R124785	♣K080496HD
Belt - Fan .....	R131213	♣K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>John Deere 6-Cyl. 466 Diesel</b>		
1996-1995		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R124786	♣K080760HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R124785	♣K080496HD
Belt - Fan .....	R131213	♣K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8300T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
1999-1997		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R124786	♣K080760HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R124785	♣K080496HD
Belt - Fan .....	R131213	♣K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8310</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2001-1999		
Belt - Air Brake Compr. ....	R157688	♣K080760HD
Belt - Fan .....	R131213	♣K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8310R; 8310RT</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014-2011		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	♣K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	♣K080510HD
Idler Pulley .....	RE232483	38076
<b>8310T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2001-2000		
Belt - Fan .....	R131213	♣K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8320</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2005-2003		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	♣K080855HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>8320 - Continued</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel - Continued</b>		
2005-2003 - Continued		
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	♣K080710HD
Tensioner Pulley - Alt. & A.C. ....	RE184034	36091
2002		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	♣K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	♣K080710HD
Belt - Fan .....	R164820	♣K080468HD
Tensioner Pulley .....	RE184034	36091
<b>8320R; 8320RT</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014		
Tensioner Assy.; W/O Air Brake Compr. ....	RE232242	38507
Idler Pulley .....	RE232483	38076
2010		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	♣K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	♣K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
<b>8320T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2005-2002		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	♣K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	♣K080710HD
Belt - Fan .....	R164820	♣K080468HD
<b>8330; 8330T</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2009-2008		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	♣K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	♣K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
<b>8335R</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014-2012		
Tensioner Assy.; W/O Air Brake Compr. ....	RE232242	38507
Idler Pulley .....	RE232483	38076
2011		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	♣K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	♣K080510HD
Tensioner Assy.; W/O Air Brake Compr. ....	RE232242	38507
Idler Pulley .....	RE232483	38076
<b>8335RT</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014-2011		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	♣K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	♣K080510HD
Idler Pulley .....	RE232483	38076
<b>8345R; 8345RT</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014		
Tensioner Assy.; W/O Air Brake Compr. ....	RE232242	38507
Idler Pulley .....	RE232483	38076
2010		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	♣K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	♣K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
<b>8360R; 8360RT</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014-2011		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	♣K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	♣K080510HD
Idler Pulley .....	RE232483	38076

♣Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>8370R; 8370RT</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014		
Tensioner Assy.; W/O Air Brake Compr. ....	RE232242	38507
Idler Pulley .....	RE232483	38076
<b>8400</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
1999-1995		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R124786	▲K080760HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R124785	▲K080496HD
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8400T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
1999-1997		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R124786	▲K080760HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R124785	▲K080496HD
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8410</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2001-2000		
Belt - Air Brake Compr. ....	R157688	▲K080760HD
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8410T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2001-2000		
Belt - Fan .....	R131213	▲K140279HD
Tensioner Assy. - Fan .....	RE69083	38621
<b>8420</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2005-2004		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Belt - Fan .....	R164820	▲K080468HD
Tensioner Pulley - Alt. & A.C. ....	RE184034	36091
2003-2002		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Belt - Fan .....	R164820	▲K080468HD
Tensioner Pulley .....	RE184034	36091
<b>8420T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2005-2002		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Belt - Fan .....	R164820	▲K080468HD
<b>8430</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2009-2008		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	▲K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	▲K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
<b>John Deere 6-Cyl. 466 Diesel</b>		
1978		
Belt - A.C. ....	R46098	▲9415HD
Belt - Air Brake Compr. ....	R210808	▲K080830HD
Belt - Fan & Alt.; W/66 1/8" Belt O.C. ....	AR70663	②TR22657
Belt - Fan & Alt.; W/66 3/8" Belt O.C. ....	AR74662	②▲9660HD
Tensioner Assy. - Air Brake Compr. ....	RE243199	38613
Hose - Upper - Pipe To Rad. ....		24236
Hose - Lower - Eng. To Pipe .....		20564
Hose - By Pass - Front .....		③<20802
Hose - By Pass - Rear .....		28443

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>8430 - Continued</b>		
<b>John Deere 6-Cyl. 466 Diesel - Continued</b>		
1977-1975		
Belt - A.C. ....	R46098	▲9415HD
Belt - Fan & Alt.; W/66 1/8" Belt O.C. ....	AR70663	②TR22657
Belt - Fan & Alt.; W/66 3/8" Belt O.C. ....	AR74662	②▲9660HD
Hose - Upper - Pipe To Rad. ....		24236
Hose - Lower - Eng. To Pipe .....		20564
Hose - By Pass - Front .....		③<20802
Hose - By Pass - Rear .....		28443
<b>8430T</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2009-2008		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	▲K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	▲K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
<b>8440</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1982-1979		
Belt - A.C. ....	R71603	▲9415HD
Belt - Fan & Alt. ....	AR74662	②▲9660HD
Hose - Upper - Eng. To Pipe .....		③<20369
Hose - Upper - Pipe To Rad. ....		24236
Hose - Lower - Eng. To Pipe .....		24438
<b>8450</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1988-1982		
Belt - A.C. ....	R73189	▲9430HD
Belt - Alt. ....	R71603	▲9415HD
Belt - Fan .....	AR57266	②▲9630HD
Hose - Upper .....		24240
Hose - Lower .....		24444
<b>8520</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2005-2004		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Belt - Fan .....	R164820	▲K080468HD
Tensioner Pulley - Alt. & A.C. ....	RE184034	36091
2003-2002		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Belt - Fan .....	R164820	▲K080468HD
Tensioner Pulley .....	RE184034	36091
<b>8520T</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2005-2002		
Belt - Alt. & A.C.; W/Air Brake Compr. ....	R228566	▲K080855HD
Belt - Alt. & A.C.; W/O Air Brake Compr. ....	R228118	▲K080710HD
Belt - Fan .....	R164820	▲K080468HD
<b>8530</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2009-2008		
Belt - Serpentine; W/Air Brake Compr. ....	R210808	▲K080830HD
Belt - Serpentine; W/O Air Brake Compr. ....	R211183	▲K080510HD
Tensioner Assy. - Serpentine .....	RE243199	38613
Alt. Decoupler Pulley Tool .....		91024
<b>8560</b>		
<b>John Deere 6-Cyl. 466 Diesel</b>		
1993-1989		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan & Alt. ....	AT58166	②▲9610HD

②Two Required ③Cut to Fit ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>8630</b>		
<b>John Deere 6-Cyl. 619 Diesel</b>		
1978-1975		
Belt - A.C. ....	R49422	▲9430HD
Belt - Fan & Alt. ....	AR70413	②▲9670HD
Hose - Upper - Eng. To Pipe .....		20530
Hose - Upper - Pipe To Rad.; W/2 1/2" I.D. Hose .....		24240
Hose - Upper - Pipe To Rad.; W/2 1/4" I.D. Hose .....		24436
Hose - Lower - Eng. To Pipe .....		24444
Hose - Lower - Pipe To Rad. ....		24444
Hose - By Pass - Front .....		24216
Hose - By Pass - Rear .....		≧20267
<b>8640</b>		
<b>John Deere 6-Cyl. 619 Diesel</b>		
1982-1979		
Belt - A.C. ....	R71603	▲9415HD
Belt - Fan & Alt. ....	AR87671	②▲9700HD
Hose - Upper - Eng. To Pipe .....		≧20172
Hose - Upper - Pipe To Rad. ....		24236
<b>8650</b>		
<b>John Deere 6-Cyl. 619 Diesel</b>		
1988-1982		
Belt - A.C. ....	R73189	▲9430HD
Belt - Alt.; W/110A. Alt. ....	R76835	▲9412HD
Belt - Fan; W/67 1/4" Belt O.C. ....		③▲9670HD
Belt - Fan; W/68 1/4" Belt O.C. ....		③▲9680HD
Hose - Lower - Eng. To Pipe .....		≧21135
Hose - Lower - Pipe To Rad. ....		24240
		or ●26529
<b>8760</b>		
<b>John Deere 6-Cyl. 619 Diesel</b>		
1993-1989		
Belt - A.C. ....	R73189	▲9430HD
Belt - Fan .....	RE37311	②TR24562
Belt - W.P. ....	RE37851	②▲9680HD
Hose - Upper .....		②24232
Hose - Lower - Eng. To Pipe .....		●25484
Hose - Lower - Pipe To Rad. ....		24444
<b>8770</b>		
<b>John Deere 6-Cyl. 619 Diesel</b>		
1996		
Belt - A.C. ....	R116308	▲9405HD
Belt - Alt. ....	RE37851	②▲9680HD
1995-1993		
Belt - W.P. & Alt. ....	RE37851	②▲9680HD
<b>8850</b>		
<b>John Deere V-8 955 Diesel</b>		
1988-1982		
Belt - A.C. ....	R69393	▲9560HD
Belt - Alt. ....	R77252	▲9380HD
Hose - Upper - Eng. To Pipe .....		②24234
Hose - Upper - Pipe To Rad. ....		24434
<b>8870</b>		
<b>John Deere 6-Cyl. 619 Diesel</b>		
1996-1993		
Belt - W.P. & Alt. ....	RE37851	②▲9680HD
<b>8960</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1993-1989		
Belt - A.C. ....	R73189	▲9430HD
Belt - W.P. ....	217638	▲K060435HD
Hose - Upper - Pipe To Rad. ....		24240
Hose - Lower - Eng. To Pipe .....		24440

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9100</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2001-1996		
Belt - Fan & Alt. ....	R135597	▲K080733HD
Tensioner Assy. - Fan & Alt. ....	RE68715	38507
Tensioner Pulley - Fan & Alt. ....	RE505264	36091
<b>9120</b>		
<b>John Deere 6-Cyl. 8.1 L Diesel</b>		
2008-2002		
Belt - Fan .....	R175712	▲K080738HD
<b>9200</b>		
<b>John Deere 6-Cyl. 10.5 L Diesel</b>		
2001-1997		
Belt - Fan; W/60 1/2" Belt O.C. ....	R131083	▲K120594HD
Tensioner Assy. - Alt. & A.C. ....	RE70535	38507
Tensioner Assy. - Fan .....	RE64442	38530
Tensioner Pulley - Alt. & A.C. ....	RE70535	36091
1996		
Belt - Fan; W/60 1/2" Belt O.C. ....	R131083	▲K120594HD
Tensioner Assy. - Alt. & A.C. ....	RE70535	38507
Tensioner Assy. - Fan .....	RE64442	38530
Tensioner Pulley - Fan & A.C. ....	RE70535	36091
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2001-1997		
Tensioner Assy. - Alt. & A.C. ....	RE70535	38507
Tensioner Assy. - Fan .....	RE64442	38530
Tensioner Pulley - Alt. & A.C. ....	RE70535	36091
1996		
Tensioner Assy. - Fan .....	RE64442	38530
Tensioner Assy. - Fan & Alt. ....	RE70535	38507
Tensioner Pulley - Fan & Alt. ....	RE70535	36091
<b>9220</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2008-2002		
Belt - Alt. & A.C. ....	R190199	▲K080745HD
Belt - Fan; W/60 1/2" Belt O.C. ....	R131083	▲K120594HD
Tensioner Assy. - Fan .....	RE249801	38530
<b>9230</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2011-2008		
Belt - Serpentine .....	R230995	▲K080570HD
Tensioner Assy. ....	RE232242	38507
<b>9300</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2001-1996		
Belt - Fan; W/60 1/2" Belt O.C. ....	R131083	▲K120594HD
Tensioner Assy. - Fan .....	RE64442	38530
Tensioner Assy. - Fan & Alt. ....	RE70535	38507
Tensioner Pulley - Fan & Alt. ....	RE70535	36091
<b>9300T</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2000-1999		
Belt - Alt. & A.C. ....	R175826	▲K080765HD
Belt - Fan .....	R175825	▲K120610HD
Tensioner Assy. - Alt. & A.C. ....	RE70535	38507
Tensioner Assy. - Fan .....	RE64442	38530
Tensioner Assy. - Fan & Alt. ....	RE70535	38507
Tensioner Pulley - Alt. & A.C. ....	RE70535	36091
Tensioner Pulley - Fan & Alt. ....	RE70535	36091
<b>9320</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2008-2002		
Belt - Alt. & A.C. ....	R190199	▲K080745HD
Belt - Fan; W/60 1/2" Belt O.C. ....	R131083	▲K120594HD
Tensioner Assy. - Fan .....	RE249801	38530

②Two Required ③Three Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9320T</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2008-2002		
Belt - Alt. & A.C. ....	R199163	♣K080745HD
Belt - Fan .....	R131083	♣K120594HD
Tensioner Assy. - Fan .....	RE249801	38530
<b>9330</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>		
2011		
Belt - Accessory Drive .....	R241746	♣K080994HD
Tensioner Assy. - Accessory Drive .....	RE243154	38630
Idler Pulley - Smooth .....	RE232483	38076
2010		
Belt - Accessory Drive .....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
Idler Pulley - Smooth .....	RE232483	38076
2009		
Belt - Serpentine .....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
2008		
Belt - Serpentine .....	R241746	♣K080994HD
Belt - Alt. ....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
Tensioner Assy. - Alt. ....	RE243154	38630
Idler Pulley - Alt. (Upper) .....	RE232483	38076
<b>9360R</b>		
<b>John Deere 6-Cyl. 9.0 L Diesel</b>		
2014-2012		
Tensioner Assy. ....	RE243154	38630
<b>9400</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2001-1996		
Belt - Fan; W/60 1/2" Belt O.C. ....	R131083	♣K120594HD
Tensioner Assy. - Fan .....	RE64442	38530
Tensioner Assy. - Fan & Alt. ....	RE70535	38507
Tensioner Pulley - Fan & Alt. ....	RE70535	36091
<b>9400T</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2001		
Belt - Alt. & A.C. ....	R175826	♣K080765HD
Belt - Fan .....	R175825	♣K120610HD
Tensioner Assy. - Alt. & A.C. ....	RE70535	38507
Tensioner Assy. - Fan .....	RE64442	38530
Tensioner Pulley - Alt. & A.C. ....	RE70535	36091
2000-1999		
Belt - Alt. & A.C. ....	R175826	♣K080765HD
Belt - Fan .....	R175825	♣K120610HD
Tensioner Assy. - Alt. & A.C. ....	RE70535	38507
Tensioner Assy. - Fan .....	RE64442	38530
Tensioner Assy. - Fan & Alt. ....	RE70535	38507
Tensioner Pulley - Alt. & A.C. ....	RE70535	36091
Tensioner Pulley - Fan & Alt. ....	RE70535	36091
<b>9420</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2008-2002		
Belt - Alt. & A.C. ....	R190199	♣K080745HD
Belt - Fan; W/60 1/2" Belt O.C. ....	R131083	♣K120594HD
Tensioner Assy. - Fan .....	RE249801	38530
<b>9420T</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2008-2002		
Belt - Alt. & A.C. ....	R199163	♣K080745HD
Belt - Fan .....	R131083	♣K120594HD
Tensioner Assy. - Fan .....	RE249801	38530

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>9430</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>		
2011-2010		
Belt - Accessory Drive .....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
Idler Pulley - Smooth .....	RE232483	38076
2009		
Belt - Serpentine .....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
2008		
Belt - Serpentine .....	R241746	♣K080994HD
Belt - Alt. ....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
Tensioner Assy. - Alt. ....	RE243154	38630
Idler Pulley - Alt. (Upper) .....	RE232483	38076
<b>9430 Scraper</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>		
2010		
Belt - Accessory Drive .....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
Idler Pulley - Smooth .....	RE232483	38076
<b>9430T</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>		
2011-2010		
Belt - Accessory Drive .....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
Idler Pulley - Smooth .....	RE232483	38076
2009		
Belt - Serpentine .....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
2008		
Belt - Serpentine .....	R241746	♣K080994HD
Belt - Alt. ....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
Tensioner Assy. - Alt. ....	RE243154	38630
Idler Pulley - Alt. (Upper) .....	RE232483	38076
<b>9520</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2008-2004		
Belt - Alt. & A.C. ....	R190199	♣K080745HD
Belt - Fan; W/60 1/2" Belt O.C. ....	R131083	♣K120594HD
Tensioner Assy. - Fan .....	RE249801	38530
2003		
Belt - Alt. & A.C. ....	R199163	♣K080745HD
Belt - Fan; W/60 1/2" Belt O.C. ....	R131083	♣K120594HD
Tensioner Assy. - Fan .....	RE249801	38530
2002		
Belt - Alt. & A.C. ....	R190199	♣K080745HD
Belt - Fan; W/60 1/2" Belt O.C. ....	R131083	♣K120594HD
Tensioner Assy. - Fan .....	RE249801	38530
<b>9520T</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>		
2008-2002		
Belt - Alt. & A.C. ....	R199163	♣K080745HD
Belt - Fan .....	R131083	♣K120594HD
Tensioner Assy. - Fan .....	RE249801	38530
<b>9530</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>		
2011-2010		
Belt - Accessory Drive .....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
Idler Pulley - Smooth .....	RE232483	38076
2009		
Belt - Serpentine .....	R241746	♣K080994HD
Tensioner Assy. ....	RE243154	38630
2008		
Belt - Serpentine .....	R241746	♣K080994HD
Belt - Alt. ....	R241746	♣K080994HD

♣Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.	Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>			<b>JOHN DEERE - Continued</b>		
<b>9530 – Continued</b>			<b>9630T – Continued</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel – Continued</b>			<b>John Deere 6-Cyl. 13.5 L Diesel – Continued</b>		
<b>2008 – Continued</b>			<b>2009</b>		
Tensioner Assy. ....	RE243154	38630	Belt - Serpentine .....	R241746	♣K080994HD
Tensioner Assy. - Alt. ....	RE243154	38630	Tensioner Assy. ....	RE243154	38630
Idler Pulley - Alt. (Upper) .....	RE232483	38076			
<b>9530 Scraper</b>			<b>2008</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>			Belt - Alt. ....		
<b>2010</b>			Tensioner Assy. - Alt. ....		
Belt - Accessory Drive .....	R241746	♣K080994HD	Idler Pulley - Alt. (Upper) .....	RE232483	38076
Tensioner Assy. ....	RE243154	38630			
Idler Pulley - Smooth .....	RE232483	38076			
<b>9530T</b>			<b>A</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>			<b>John Deere 2-Cyl. 309</b>		
<b>2011-2010</b>			<b>1939-1934</b>		
Belt - Accessory Drive .....	R241746	♣K080994HD	Belt - Gen.; Ser. No. 542718 Thru 583999 ..	A3037R	♣9330HD
Tensioner Assy. ....	RE243154	38630	Belt - Gen.; Ser. No. 584000 & After .....	B1587R	♣9290HD
Idler Pulley - Smooth .....	RE232483	38076			
<b>2009</b>			<b>John Deere 2-Cyl. 321</b>		
Belt - Serpentine .....	R241746	♣K080994HD	<b>1952-1940</b>		
Tensioner Assy. ....	RE243154	38630	Belt - Gen.; Ser. No. 542718 Thru 583999 ..		
			Belt - Gen.; Ser. No. 584000 & After .....		
<b>2008</b>			Belt - Gen.; Ser. No. 542718 Thru 583999 ..		
Belt - Serpentine .....	R241746	♣K080994HD	Belt - Gen.; Ser. No. 584000 & After .....		
Belt - Alt. ....	R241746	♣K080994HD			
Tensioner Assy. ....	RE243154	38630	<b>AO; AR</b>		
Tensioner Assy. - Alt. ....	RE243154	38630	<b>John Deere 2-Cyl. 309</b>		
Idler Pulley - Alt. (Upper) .....	RE232483	38076	<b>1940-1936</b>		
			Belt - Gen.; Ser. No. 260000 Thru 271999 ..		
			Belt - Gen.; Ser. No. 272000 & After .....		
<b>9620; 9620T</b>			<b>John Deere 2-Cyl. 321</b>		
<b>John Deere 6-Cyl. 12.5 L Diesel</b>			<b>1953-1941</b>		
<b>2008-2004</b>			Belt - Gen.; Ser. No. 260000 Thru 271999 ..		
Belt - Alt. & A.C. ....	R199163	♣K080745HD	Belt - Gen.; Ser. No. 272000 & After .....		
Tensioner Assy. - Fan .....	RE249801	38530			
<b>9630</b>			<b>B</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>			<b>John Deere 2-Cyl. 149</b>		
<b>2011</b>			<b>1938-1935</b>		
Belt - Accessory Drive .....	R241746	♣K080994HD	Belt - Gen. ....		
Tensioner Assy. - Accessory Drive .....	RE243154	38630	Belt - W.P. & Gen. ....		
Idler Pulley - Smooth .....	RE232483	38076			
<b>2010</b>			<b>John Deere 2-Cyl. 175</b>		
Belt - Accessory Drive .....	R241746	♣K080994HD	<b>1947-1938</b>		
Tensioner Assy. ....	RE243154	38630	Belt - Gen. ....		
Idler Pulley - Smooth .....	RE232483	38076	Belt - W.P. & Gen. ....		
<b>2009</b>			<b>John Deere 2-Cyl. 190</b>		
Belt - Serpentine .....	R241746	♣K080994HD	<b>1952-1947</b>		
Tensioner Assy. ....	RE243154	38630	Belt - Gen. ....		
			Belt - W.P. & Gen. ....		
<b>2008</b>			<b>BO</b>		
Belt - Alt. ....	R241746	♣K080994HD	<b>John Deere 2-Cyl. 149</b>		
Tensioner Assy. - Alt. ....	RE243154	38630	<b>1938</b>		
Idler Pulley - Alt. (Upper) .....	RE232483	38076	Belt - Gen. ....		
			<b>1937-1936</b>		
			Belt - Gen. ....		
<b>9630 Scraper</b>			<b>John Deere 2-Cyl. 175</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>			<b>1946-1939</b>		
<b>2010</b>			Belt - Gen. ....		
Belt - Accessory Drive .....	R241746	♣K080994HD			
Tensioner Assy. ....	RE243154	38630	<b>John Deere 2-Cyl. 190</b>		
Idler Pulley - Smooth .....	RE232483	38076	<b>1947</b>		
			Belt - Gen. ....		
<b>9630T</b>			<b>BR</b>		
<b>John Deere 6-Cyl. 13.5 L Diesel</b>			<b>John Deere 2-Cyl. 149</b>		
<b>2011</b>			<b>1938-1936</b>		
Belt - Accessory Drive .....	R241746	♣K080994HD	Belt - Gen. ....		
Tensioner Assy. - Accessory Drive .....	RE243154	38630			
Idler Pulley - Smooth .....	RE232483	38076	<b>John Deere 2-Cyl. 175</b>		
<b>2010</b>			<b>1946-1939</b>		
Belt - Accessory Drive .....	R241746	♣K080994HD	Belt - Gen. ....		
Tensioner Assy. ....	RE243154	38630			
Idler Pulley - Smooth .....	RE232483	38076	<b>John Deere 2-Cyl. 190</b>		
			<b>1947</b>		
			Belt - Gen. ....		

♣Standard Belt May Also Be Available



Application	OEM No.	Our No.	Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>			<b>KIOTI - Continued</b>		
<b>D</b>			<b>CK35 - Continued</b>		
<b>John Deere 2-Cyl. 465</b>					
1927-1923					
Belt - Gen.; Ser. No. 161400 & After .....	B1587R	♣9290HD	<b>Kiotti 3-Cyl. 101 Diesel</b>		
<b>John Deere 2-Cyl. 501</b>					
1953-1927					
Belt - Gen.; Ser. No. 161400 & After .....	B1587R	♣9290HD	2010-2006		
<b>G</b>					
<b>John Deere 2-Cyl. 413</b>					
1953-1937					
Belt - Gen. ....	B1587R	♣9290HD	Belt - Fan & Alt. .... E5640-72531 ♣9412HD		
<b>M</b>					
<b>John Deere 2-Cyl. 101</b>					
1952-1947					
Belt - Gen. ....	L4201T	2230	<b>DK35SE</b>		
<b>MC; MT</b>					
<b>John Deere 2-Cyl. 101</b>					
1952-1949					
Belt - Gen. ....	L4201T	2230	<b>Dae Dong 3-Cyl. 111 Diesel</b>		
<b>R</b>					
<b>John Deere 2-Cyl. 416 Diesel</b>					
1954-1949					
Belt - Fan & Gen. ....	R221R	TR28583	2013-2007		
<b>KIOTI</b>					
<b>CK20S</b>					
<b>Dae Dong 3-Cyl. 61 Diesel</b>					
2016-2011					
Belt - Fan & Alt. ....	E5760-72532	7410	Belt - Fan & Alt. .... E5800-72531 ♣9425HD		
<b>Kiotti 3-Cyl. 61 Diesel</b>					
2010-2008					
Belt - Fan & Alt. ....	E5760-72532	7410	<b>DK40</b>		
<b>CK25</b>					
<b>Kiotti 3-Cyl. 79 Diesel</b>					
2008-2004					
Belt - Fan & Alt. ....	E5522-72532	♣9415HD	<b>Kiotti 4-Cyl. 122 Diesel</b>		
<b>CK27</b>					
<b>Dae Dong 3-Cyl. 85 Diesel</b>					
2016-2011					
Belt - Fan & Alt. ....	E5522-72532	♣9415HD	2005-2001		
<b>Kiotti 3-Cyl. 85 Diesel</b>					
2010-2008					
Belt - Fan & Alt. ....	E5522-72532	♣9415HD	Belt - Fan & Alt. .... A39		
<b>CK30</b>					
<b>Dae Dong 3-Cyl. 92 Diesel</b>					
2016-2011					
Belt - Fan & Alt. ....	E5522-72532	♣9415HD	<b>DK45</b>		
<b>Kiotti 3-Cyl. 92 Diesel</b>					
2010-2004					
Belt - Fan & Alt. ....	E5522-72532	♣9415HD	<b>Kiotti 4A220 Diesel</b>		
<b>CK35</b>					
<b>Dae Dong 3-Cyl. 101 Diesel</b>					
2016-2011					
Belt - Fan & Alt. ....	E5640-72531	♣9412HD	2005-2000		
<b>DK45</b>					
<b>Kiotti 4-Cyl. 122 Diesel</b>					
2004-2000					
Belt - Fan & Alt. ....	A39		<b>DK50</b>		
<b>DK50SE</b>					
<b>Dae Dong 4-Cyl. 149 Diesel</b>					
2015-2011					
Belt - Fan & Alt. ....	E5800-72531	♣9425HD	<b>Kiotti 4-Cyl. 122 Diesel</b>		
<b>Kiotti 4-Cyl. 149 Diesel</b>					
2010					
Belt - Fan & Alt. ....	E5800-72531	♣9425HD	2004-2000		
<b>DK55</b>					
<b>Kiotti 4-Cyl. 134 Diesel</b>					
2008-2003					
Belt - Fan & Alt. ....	A39		<b>DK65</b>		
<b>DK65</b>					
<b>Kiotti 3-Cyl. 165 Diesel</b>					
2004-2001					
Belt - Fan & Alt. ....	A68		<b>DK75</b>		
<b>DK75</b>					
<b>Perkins 4-Cyl. 268 Diesel</b>					
2011-2008					
Belt - A.C. ....	E7310-72612	♣9490HD	Belt - Fan .... E7240-72531 ♣9520HD		
Belt - Fan ....	E7240-72531	♣9520HD	<b>DK90</b>		
<b>DK90</b>					
<b>Perkins 4-Cyl. 268 Diesel</b>					
2015-2007					
Belt - A.C. ....	E7310-72612	♣9490HD	Belt - Fan .... E7240-72531 ♣9520HD		
Belt - Fan ....	E7240-72531	♣9520HD	<b>DK4510; DK5010; DK5510</b>		
<b>DK4510; DK5010; DK5510</b>					
<b>Dae Dong 3-Cyl. 111 Diesel</b>					
2017-2015					
Belt - Fan ....	F6800-72531	♣9447HD	<b>DS3510</b>		
<b>DS3510</b>					
<b>Dae Dong 3-Cyl. 101 Diesel</b>					
2015-2011					
Belt - Fan & Alt. ....	E5640-72531	♣9412HD			

♣Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>KIOTI - Continued</b>		
<b>DS4510</b>		
Dae Dong 4-Cyl. 134 Diesel		
2015-2011		
Belt - Fan & Alt. ....	E5800-72531	▲9425HD
<b>LB1914</b>		
Dae Dong TD950 Diesel		
2007-1991		
Belt - Fan & Alt. ....		▲9365HD
<b>LK2552</b>		
Kioti TD1300F-1 Diesel		
2001-1997		
Belt - Fan & Alt. ....		▲9425HD
<b>LK2554</b>		
Kioti TD1300F-1 Diesel		
2004-1993		
Belt - Fan & Alt. ....		▲9425HD
<b>LK3052</b>		
Kioti TD1400 Diesel		
2001-1999		
Belt - Fan & Alt. ....		▲9425HD
<b>LK3054</b>		
Kioti TD1400 Diesel		
2004-1992		
Belt - Fan & Alt. ....		▲9425HD
<b>NX4510; NX5010; NX5510; NX6010</b>		
Dae Dong 3-Cyl. 111 Diesel		
2017-2014		
Belt - Fan ....	F6800-72531	▲9447HD
<b>PX9020</b>		
Perkins 4-Cyl. 269 Diesel		
2015-2014		
Belt - A.C. ....	E7251-72531	▲9463HD
Belt - Fan ....	E7240-72531	▲9520HD
<b>RX6010</b>		
Dae Dong 4-Cyl. 149 Diesel		
2015-2012		
Belt - A.C. ....	E7220-72611	▲9610HD
<b>RX6010C</b>		
Dae Dong 4-Cyl. 149 Diesel		
2011		
Belt - A.C. ....	E7220-72611	▲9610HD
<b>RX6620; RX7320</b>		
Dae Dong 4-Cyl. 149 Diesel		
2015-2014		
Belt - Fan ....	F6800-72531	▲9447HD
<b>KUBOTA</b>		
<b>B20</b>		
Kubota D950AT Diesel		
1998-1990		
Belt - Fan & Alt. ....		7365
Hose - Upper ....		≡21391
Hose - Lower ....		24216
Hose - By Pass ....		28439

Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>B21</b>		
Kubota 3-Cyl. 61 Diesel		
2009-1996		
Belt - Fan & Alt. ....		7385
<b>B1550</b>		
Kubota 3-Cyl. 52 Diesel		
1998-1988		
Belt - Fan & Alt. ....		7365
Hose - Upper ....		●25154
<b>B1700</b>		
Kubota 3-Cyl. 55 Diesel		
2000-1997		
Belt - Fan & Alt. ....	1948272530	3V375
<b>B1750</b>		
Kubota 3-Cyl. 57 Diesel		
1996-1988		
Belt - Fan & Alt. ....		7365
Hose - Upper ....		≡21391
Hose - Lower ....		24216
Hose - By Pass ....		28439
<b>B2100</b>		
Kubota 3-Cyl. 61 Diesel		
2000-1995		
Belt - Fan & Alt. ....	1948272530	3V375
<b>B2150</b>		
Kubota 4-Cyl. 75 Diesel		
1999-1988		
Belt - Fan & Alt. ....		7365
Hose - Upper ....		≡21391
Hose - Lower ....		24216
Hose - Lower - Pipe To Rad. ....		24216
Hose - By Pass ....		28439
<b>B2320</b>		
Kubota 3-Cyl. 61 Diesel		
2014-2010		
Belt - Blade Drive; W/54" Deck ....	K5351-34710	6796BR
Belt - Blade Drive; W/60" Deck ....	K5763-34712	7103BR
Belt - Fan ....	16241-97010	7370
<b>B2400</b>		
Kubota 3-Cyl. 68 Diesel		
2000-1995		
Belt - Fan & Alt. ....	1948272530	3V375
<b>B2410</b>		
Kubota 3-Cyl. 68 Diesel		
2005-2001		
Belt - Fan & Alt. ....	14911-97010	6738
<b>B2620</b>		
Kubota 3-Cyl. 68 Diesel		
2014-2008		
Belt - Blade Drive; W/54" Deck ....	K5351-34710	6796BR
Belt - Blade Drive; W/60" Deck ....	K5763-34712	7103BR
Belt - Fan ....	16241-97010	7370
<b>B2630</b>		
Kubota 3-Cyl. 68 Diesel		
2012-2009		
Belt - Blade Drive; W/60" Deck ....	K5763-34710	7103BR
Belt - Blade Drive; W/72" Deck ....	K5671-34710	7104BR
Belt - Fan ....	16241-97010	7370
2008-2007		
Belt - Alt. ....	16241-97010	7370
Belt - Blade Drive; W/60" Deck ....	K5763-34710	7103BR
Belt - Blade Drive; W/72" Deck ....	K5671-34710	7104BR

≡Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>B2630 – Continued</b>		
<b>Kubota 3-Cyl. 68 Diesel – Continued</b>		
2008–2007 – Continued		
Belt - Fan .....	16241-97010	7370
2006–2005		
Belt - Blade Drive; W/60" Deck .....	K5763-34710	7103BR
Belt - Blade Drive; W/72" Deck .....	K5671-34710	7104BR
Belt - Fan .....	16241-97010	7370
<b>B2710</b>		
<b>Kubota 4-Cyl. 82 Diesel</b>		
2005–2002		
Belt - Fan .....	16241-97010	7370
<b>B2910</b>		
<b>Kubota 4-Cyl. 91 Diesel</b>		
2005–2000		
Belt - Fan & Alt. ....	14911-97010	6738
<b>B2920</b>		
<b>Kubota 3-Cyl. 77 Diesel</b>		
2014–2010		
Belt - Blade Drive; W/54" Deck .....	K5351-34710	6796BR
Belt - Blade Drive; W/60" Deck .....	K5763-34712	7103BR
Belt - Fan .....	16241-97010	7370
2009		
Belt - Blade Drive; W/54" Deck .....	K5351-34710	6796BR
Belt - Blade Drive; W/60" Deck .....	K5763-34712	7103BR
2008		
Belt - Blade Drive; W/54" Deck .....	K5351-34710	6796BR
Belt - Blade Drive; W/60" Deck .....	K5763-34712	7103BR
Belt - Fan .....	16241-97010	7370
<b>B3200</b>		
<b>Kubota 4-Cyl. 91 Diesel</b>		
2014–2009		
Belt - Blade Drive; W/60" Deck .....	K5763-34710	7103BR
Belt - Blade Drive; W/72" Deck .....	K5671-34710	7104BR
Belt - Fan .....	16241-97010	7370
<b>B4200</b>		
<b>Kubota 2-Cyl. 35 Diesel</b>		
1996–1987		
Belt - Fan .....		7300
<b>B5100</b>		
<b>Kubota 2-Cyl. 31 Diesel</b>		
1984–1978		
Belt - Fan .....	1523172530	7300
<b>B5200</b>		
<b>Kubota 3-Cyl. 46 Diesel</b>		
1996–1983		
Belt - Fan & Alt. ....		7360
Hose - Upper .....		☞21488
Hose - Lower - Eng. To Pipe .....		21258
Hose - Lower - Pipe To Rad. ....		☞21942
<b>B6000</b>		
<b>Kubota 2-Cyl. 35 Diesel</b>		
1978–1973		
Belt - Fan .....	1523172530	7300
Hose - Upper .....		☞20661
		or ●25251
Hose - Lower .....		☞20774
<b>B6100</b>		
<b>Kubota 3-Cyl. 41 Diesel</b>		
1984–1978		
Belt - Fan .....	1523172530	7300

Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>B6200</b>		
<b>Kubota 3-Cyl. 52 Diesel</b>		
1996–1983		
Belt - Fan & Alt. ....		7365
Hose - Upper .....		☞21488
Hose - Lower - Eng. To Pipe .....		21258
Hose - Lower - Pipe To Rad. ....		☞21942
<b>B7100</b>		
<b>Kubota 3-Cyl. 47 Diesel</b>		
1999–1980		
Belt - Fan .....	1523172530	7300
Hose - Upper .....		☞20065
1979–1977		
Belt - Fan .....	1523172530	7300
<b>B7200</b>		
<b>Kubota 3-Cyl. 57 Diesel</b>		
1991–1983		
Belt - Fan & Alt. ....		7360
Hose - Upper .....		☞21488
Hose - Lower - Eng. To Pipe .....		21258
Hose - Lower - Pipe To Rad. ....		☞21942
<b>B7300</b>		
<b>Kubota 3-Cyl. 43 Diesel</b>		
1999–1997		
Belt - Fan & Alt. ....	REMF1345	7345
<b>B7400</b>		
<b>Kubota 3-Cyl. 44 Diesel</b>		
2003–2000		
Belt - Fan & Alt. ....	1G027-97010	7340
<b>B7410</b>		
<b>Kubota 3-Cyl. 44 Diesel</b>		
2004		
Belt - Alt. ....	1G027-97010	7340
<b>Kubota 3-Cyl. 47 Diesel</b>		
2008–2005		
Belt - Fan .....	1G027-97010	7340
<b>B7500</b>		
<b>Kubota 3-Cyl. 61 Diesel</b>		
2003–2000		
Belt - Alt. ....		7370
<b>B7510</b>		
<b>Kubota 3-Cyl. 61 Diesel</b>		
2008–2007		
Belt - Aux. Alt. ....	14911-97010	6738
Belt - Fan .....	16241-97010	7370
2006–2004		
Belt - Fan & Alt. ....	16241-97010	7370
<b>B7610</b>		
<b>Kubota 3-Cyl. 68 Diesel</b>		
2008–2007		
Belt - Aux. Alt. ....	14911-97010	6738
Belt - Fan .....	16241-97010	7370
2006		
Belt - Fan & Alt. ....	16241-97010	7370
2004		
Belt - Fan & Alt. ....	16241-97010	7370
<b>B7800</b>		
<b>Kubota 4-Cyl. 91 Diesel</b>		
2009		
Belt - Fan .....	16241-97010	7370

☞Cut to Fit ●Flexible Coolant Hose



Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>B7800 – Continued</b>		
<b>Kubota 4-Cyl. 91 Diesel – Continued</b>		
2008–2006		
Belt - Alt. ....	16241-97010	7370
2005		
Belt - Alt. ....		7370
2004		
Belt - Alt. ....	16241-97010	7370
2003		
Belt - Alt. ....		7370
<b>B8200</b>		
<b>Kubota 3-Cyl. 57 Diesel</b>		
1991–1981		
Belt - Fan & Alt. ....		7300
Hose - Upper ....		≧21488
Hose - Lower - Eng. To Pipe ....		21258
Hose - Lower - Pipe To Rad. ....		24218
<b>B9200</b>		
<b>Kubota 4-Cyl. 75 Diesel</b>		
1991–1987		
Belt - Fan & Alt. ....		7300
Hose - Upper ....		≧21488
Hose - Lower - Eng. To Pipe ....		21258
Hose - Lower - Pipe To Rad. ....		24218
<b>BX22</b>		
<b>Kubota 3-Cyl. 55 Diesel</b>		
2003–2002		
Belt - Fan & Alt. ....	16241-97010	7370
<b>BX23</b>		
<b>Kubota 3-Cyl. 55 Diesel</b>		
2005–2004		
Belt - Fan & Alt. ....	16241-97010	7370
<b>BX24</b>		
<b>Kubota 3-Cyl. 55 Diesel</b>		
2008		
Belt - Alt. ....	16883-97010	7350
2007–2006		
Belt - Alt. ....		7350
<b>BX25D</b>		
<b>Kubota 3-Cyl. 55 Diesel</b>		
2014–2013		
Belt - Fan ....	16883-97010	7350
<b>BX1500</b>		
<b>Kubota 2-Cyl. 37 Diesel</b>		
2006–2003		
Belt - Fan & Alt. ....	15881-97010	7345
<b>BX1800</b>		
<b>Kubota 3-Cyl. 44 Diesel</b>		
2003–2000		
Belt - Fan & Alt. ....	15881-97010	7345
<b>BX1830</b>		
<b>Kubota 3-Cyl. 44 Diesel</b>		
2005–2004		
Belt - Fan & Alt. ....	15881-97010	7345
<b>BX1870</b>		
<b>Kubota 3-Cyl. 44 Diesel</b>		
2014–2013		
Belt - Fan ....	15881-97010	7345

Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>BX2200</b>		
<b>Kubota 3-Cyl. 55 Diesel</b>		
2003–2000		
Belt - Fan & Alt. ....	16241-97010	7370
<b>BX2230</b>		
<b>Kubota 3-Cyl. 55 Diesel</b>		
2005–2004		
Belt - Fan & Alt. ....	16883-97010	7350
<b>BX2370</b>		
<b>Kubota 3-Cyl. 55 Diesel</b>		
2014–2013		
Belt - Fan ....	16883-97010	7350
<b>L35</b>		
<b>Kubota 3-Cyl. 101 Diesel</b>		
2004–1994		
Belt - Fan & Alt. ....	15469-97010	♣9425HD
<b>L48</b>		
<b>Kubota 4-Cyl. 149 Diesel</b>		
2009–2000		
Belt - Fan ....	15196-97010	♣9430HD
<b>L175</b>		
<b>Kubota 2-Cyl. 45 Diesel</b>		
1977–1973		
Belt - Fan & Alt. ....		7400
Hose - Upper ....		≧20065
Hose - Lower ....		≧20065
<b>L185</b>		
<b>Kubota 2-Cyl. 45 Diesel</b>		
1982–1976		
Belt - Fan & Alt.; W/40 1/8" Belt O.C. ....		7400
Belt - Fan & Alt.; W/41 1/8" Belt O.C. ....		7410
<b>L200</b>		
<b>Kubota 2-Cyl. 65 Diesel</b>		
1973–1972		
Belt - Fan & Alt. ....		♣9490HD
<b>L210</b>		
<b>Kubota 2-Cyl. 65 Diesel</b>		
1973–1972		
Belt - Fan & Alt. ....		♣9490HD
Hose - Upper ....		●25476
Hose - Lower ....		24226
<b>L225</b>		
<b>Kubota 3-Cyl. 68 Diesel</b>		
1977–1973		
Belt - Fan & Alt. ....	FM41	7410
Hose - Upper ....		≧20065
Hose - Lower ....		≧20065
<b>L235</b>		
<b>Kubota 3-Cyl. 68 Diesel</b>		
1985–1981		
Belt - Fan & Alt. ....		7417
Hose - Upper ....		≧20065
		or ●25472
Hose - Lower ....		≧21260
<b>L245</b>		
<b>Kubota 3-Cyl. 68 Diesel</b>		
1989–1976		
Belt - Fan & Alt.; W/41 5/8" Belt O.C. ....		7417
Belt - Fan & Alt.; W/42 5/8" Belt O.C. ....		7425
Hose - Upper ....		≧20661
		or ●25249

≧Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>L260</b>		
<b>Kubota 2-Cyl. 78 Diesel</b>		
1976-1973		
Belt - Fan & Gen. ....	1512172532	▲9440HD
Hose - Upper .....		●25249
Hose - Lower .....		●25250
<b>L275</b>		
<b>Kubota 3-Cyl. 79 Diesel</b>		
1985-1981		
Belt - Fan & Alt. ....		7365
Hose - Upper .....		☞20065
	or	●25472
Hose - Lower .....		☞21260
<b>L285</b>		
<b>Kubota 4-Cyl. 91 Diesel</b>		
1981-1975		
Belt - Fan & Alt.; W/41 5/8" Belt O.C. ....		7417
Belt - Fan & Alt.; W/42 5/8" Belt O.C. ....	1540197011	7425
Hose - Upper .....		☞20065
Hose - Lower .....		☞20065
<b>L295</b>		
<b>Kubota 3-Cyl. 79 Diesel</b>		
1982-1978		
Belt - Fan & Alt. ....		7410
<b>L305</b>		
<b>Kubota 3-Cyl. 79 Diesel</b>		
1985-1980		
Belt - Fan & Alt. ....		7417
Hose - Upper .....		●25250
Hose - Lower .....		●25251
<b>L345</b>		
<b>Kubota 4-Cyl. 91 Diesel</b>		
1986-1978		
Belt - Fan & Alt. ....		7425
Hose - Lower .....		☞21794
<b>L355</b>		
<b>Kubota 4-Cyl. 106 Diesel</b>		
1989-1982		
Belt - Fan & Alt. ....		▲9425HD
Hose - Upper .....		☞20065
	or	●25472
Hose - Lower .....		☞21260
<b>L2050</b>		
<b>Kubota 3-Cyl. 68 Diesel</b>		
1991-1989		
Belt - Fan & Alt. ....		7430
Hose - Upper .....		●25472
Hose - Lower .....		●25250
<b>L2250</b>		
<b>Kubota 3-Cyl. 79 Diesel</b>		
1991-1985		
Belt - Fan & Alt. ....		7425
Hose - Upper - Eng. To Pipe .....		●25255
Hose - Upper - Pipe To Rad. ....		24222
Hose - Lower - Eng. To Pipe .....		●25251
Hose - Lower - Pipe To Rad. ....		24220
<b>L2350</b>		
<b>Kubota 3-Cyl. 68 Diesel</b>		
1997-1991		
Belt - Fan & Alt. ....	17367-97010	7430
Hose - Upper .....		☞20065
	or	●25472

Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>L2500</b>		
<b>Kubota 3-Cyl. 85 Diesel</b>		
1999-1998		
Belt - Fan & Alt. ....	15196-97010	▲9430HD
<b>L2550</b>		
<b>Kubota 3-Cyl. 85 Diesel</b>		
1991-1985		
Belt - Fan & Alt. ....		7425
Hose - Upper - Eng. To Pipe .....		●25255
Hose - Upper - Pipe To Rad. ....		24222
Hose - Lower - Eng. To Pipe .....		●25251
Hose - Lower - Pipe To Rad. ....		24220
<b>L2600</b>		
<b>Kubota 3-Cyl. 85 Diesel</b>		
2003-2000		
Belt - Fan & Alt. ....	15196-97010	▲9430HD
<b>L2650</b>		
<b>Kubota 3-Cyl. 85 Diesel</b>		
1996-1990		
Belt - Fan & Alt. ....		7425
Hose - Upper .....		●25255
Hose - Lower .....		●25255
<b>L2800</b>		
<b>Kubota 3-Cyl. 85 Diesel</b>		
2008-2004		
Belt - Fan .....	15469-97010	▲9425HD
<b>Kubota 3-Cyl. 91 Diesel</b>		
2011-2009		
Belt - Fan .....	15469-97010	▲9425HD
<b>L2850</b>		
<b>Kubota 4-Cyl. 106 Diesel</b>		
1995-1985		
Belt - Fan & Alt. ....		▲9430HD
Hose - Upper - Eng. To Pipe .....		●25253
Hose - Upper - Pipe To Rad. ....		24222
Hose - Lower - Pipe To Rad. ....		●25250
<b>L2900</b>		
<b>Kubota 3-Cyl. 91 Diesel</b>		
1999-1994		
Belt - Fan & Alt. ....		▲9425HD
Hose - Upper .....		☞21752
	or	●25252
<b>L2950</b>		
<b>Kubota 3-Cyl. 89 Diesel</b>		
1993-1990		
Belt - Fan & Alt. ....	15401-97010	7417
<b>L3000</b>		
<b>Kubota 3-Cyl. 91 Diesel</b>		
2003-2000		
Belt - Fan & Alt. ....	15469-97010	▲9425HD
<b>L3010</b>		
<b>Kubota 3-Cyl. 91 Diesel</b>		
2002-1998		
Belt - Fan & Alt. ....		▲9425HD
<b>L3130</b>		
<b>Kubota 3-Cyl. 91 Diesel</b>		
2008-2003		
Belt - Alt. ....		▲9425HD

☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>L3200</b>		
Kubota 3-Cyl. 91 Diesel		
2014-2010		
Belt - Fan .....	15469-97010	▲9425HD
<b>L3240</b>		
Kubota 3-Cyl. 101 Diesel		
2013-2009		
Belt - Fan .....	15469-97010	▲9425HD
2008-2007		
Belt - Alt .....		7417
Belt - Fan .....	15469-97010	▲9425HD
<b>L3250</b>		
Kubota 4-Cyl. 114 Diesel		
1991-1989		
Belt - Fan & Alt. ....		▲9430HD
Hose - Upper - Eng. To Pipe .....		●25253
Hose - Upper - Pipe To Rad. ....		24222
Hose - Lower - Pipe To Rad. ....		●25250
<b>L3300</b>		
Kubota 3-Cyl. 101 Diesel		
1999-1994		
Belt - Fan & Alt. ....		▲9425HD
Hose - Upper .....		≧<21752
		or ●25252
<b>L3301</b>		
Kubota 3-Cyl. 111 Diesel		
2014		
Belt - Fan .....	15469-97010	▲9425HD
<b>L3350</b>		
Kubota 4-Cyl. 114 Diesel		
1991-1985		
Belt - Fan & Alt. ....	A41	▲9420HD
Hose - Upper .....		●25253
Hose - Lower .....		●25253
<b>L3400</b>		
Kubota 3-Cyl. 101 Diesel		
2008-2004		
Belt - Fan .....	15469-97010	▲9425HD
Kubota 3-Cyl. 111 Diesel		
2011-2009		
Belt - Fan .....	15469-97010	▲9425HD
<b>L3410</b>		
Kubota 3-Cyl. 101 Diesel		
2002-1998		
Belt - Fan & Alt. ....		▲9425HD
<b>L3430</b>		
Kubota 3-Cyl. 101 Diesel		
2008-2002		
Belt - Alt. ....		▲9425HD
<b>L3450</b>		
Kubota 4-Cyl. 114 Diesel		
1996-1990		
Belt - Fan & Alt. ....		7420
Hose - Upper .....		≧<21794
Hose - Lower .....		●25255
<b>L3540</b>		
Kubota 3-Cyl. 111 Diesel		
2013-2007		
Belt - Fan .....	15469-97010	▲9425HD

Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>L3600</b>		
Kubota 4-Cyl. 114 Diesel		
1999-1994		
Belt - Fan & Alt. ....		▲9425HD
Hose - Upper .....		≧<21752
		or ●25252
<b>L3650</b>		
Kubota 4-Cyl. 114 Diesel		
1993-1990		
Belt - Fan & Alt. ....		7420
Hose - Lower .....		●25806
<b>L3700</b>		
Kubota 3-Cyl. 111 Diesel		
2014-2010		
Belt - Fan .....	15469-97010	▲9425HD
<b>L3710</b>		
Kubota 4-Cyl. 114 Diesel		
2002-1998		
Belt - Fan & Alt. ....		▲9425HD
<b>L3750</b>		
Kubota 5-Cyl. 142 Diesel		
1991-1984		
Belt - Fan & Alt. ....		▲9430HD
<b>L3800</b>		
Kubota 3-Cyl. 111 Diesel		
2014-2010		
Belt - Fan .....	15469-97010	▲9425HD
<b>L3830</b>		
Kubota 3-Cyl. 112 Diesel		
2008-2003		
Belt - Fan & Alt. ....	15469-97010	▲9425HD
<b>L3901</b>		
Kubota 3-Cyl. 111 Diesel		
2014		
Belt - Fan .....	15469-97010	▲9425HD
<b>L3940</b>		
Kubota 4-Cyl. 122 Diesel		
2013-2007		
Belt - Fan .....	15469-97010	▲9425HD
<b>L4060</b>		
Kubota 4-Cyl. 148 Diesel		
2014-2013		
Belt - Fan .....	15469-97010	▲9425HD
<b>L4150</b>		
Kubota 5-Cyl. 142 Diesel		
1995-1984		
Belt - Fan & Alt. ....		▲9430HD
Hose - Upper .....		≧<20137
		or ●25252
<b>L4200</b>		
Kubota 4-Cyl. 134 Diesel		
1998-1993		
Belt - Fan & Alt. ....		▲9425HD
Hose - Upper .....		≧<21752
		or ●25252
<b>L4240</b>		
Kubota 4-Cyl. 134 Diesel		
2013-2009		
Belt - Fan .....	15469-97010	▲9425HD

≧<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>L4240 – Continued</b>		
Kubota 4-Cyl. 134 Diesel – Continued		
2008–2007		
Belt - Alt. ....		7417
Belt - Fan .....	15469-97010	▲9425HD
<b>L4300</b>		
Kubota 4-Cyl. 134 Diesel		
2005–2001		
Belt - Fan & Alt. ....	15471-97010	▲9420HD
<b>L4310</b>		
Kubota 4-Cyl. 134 Diesel		
2002–1998		
Belt - Fan & Alt. ....		▲9425HD
<b>L4330</b>		
Kubota 4-Cyl. 134 Diesel		
2008–2003		
Belt - Fan & Alt. ....	15469-97010	▲9425HD
<b>L4350</b>		
Kubota 4-Cyl. 134 Diesel		
1998–1990		
Belt - Fan & Alt. ....		▲9420HD
Hose - Upper .....		●25253
<b>L4400</b>		
Kubota 4-Cyl. 134 Diesel		
2011–2005		
Belt - Fan .....	15471-97010	▲9420HD
<b>L4610</b>		
Kubota 4-Cyl. 134 Diesel		
2002–2000		
Belt - Fan & Alt. ....	15469-97010	▲9425HD
<b>L4630</b>		
Kubota 4-Cyl. 134 Diesel		
2008–2003		
Belt - Fan & Alt. ....	15469-97010	▲9425HD
<b>L4701</b>		
Kubota 4-Cyl. 148 Diesel		
2014		
Belt - Fan .....	15471-97010	▲9420HD
<b>L4740</b>		
Kubota 4-Cyl. 149 Diesel		
2013–2009		
Belt - Fan .....	15469-97010	▲9425HD
2008–2007		
Belt - Alt. ....		7417
Belt - Fan .....	15469-97010	▲9425HD
<b>L4760</b>		
Kubota 4-Cyl. 148 Diesel		
2014–2013		
Belt - Fan .....	15469-97010	▲9425HD
<b>L4850</b>		
Kubota 5-Cyl. 152 Diesel		
1998–1990		
Belt - Fan & Alt. ....		▲9430HD
Hose - Lower .....		◊<20137
		or ●25477
<b>L5030</b>		
Kubota 4-Cyl. 149 Diesel		
2008–2003		
Belt - Fan & Alt. ....	15469-97010	▲9425HD

Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>L5040; L5240</b>		
Kubota 4-Cyl. 149 Diesel		
2008–2007		
Belt - Alt. ....		7425
<b>L5450</b>		
Kubota 5-Cyl. 168 Diesel		
1998–1990		
Belt - Fan & Alt. ....		▲9430HD
Hose - Upper .....		◊<20137
		or ●25252
Hose - Lower; W/Single Hose .....		◊<21103
Hose - Lower - Pipe To Rad. ....		24222
<b>L5740</b>		
Kubota 4-Cyl. 149 Diesel		
2008–2007		
Belt - Alt. ....		7425
<b>M105</b>		
Kubota 4-Cyl. 230 Diesel		
2007–2004		
Belt - A.C. ....		▲9650HD
Belt - Fan & Alt. ....		▲9500HD
<b>M110; M120</b>		
Kubota 5-Cyl. 356 Diesel		
2004–1999		
Belt - Fan & Alt. ....		▲9650HD
<b>M125X</b>		
Kubota 5-Cyl. 356 Diesel		
2011–2009		
Belt - Fan .....	3M760-15780	②7460
2008–2005		
Belt - Fan .....	3M760-15780	②7460
Belt - Fan & Alt. ....	3M760-15780	②7460
<b>M4000</b>		
Kubota 6-Cyl. 136 Diesel		
1981–1977		
Belt - Fan & Alt. ....		▲9440HD
<b>M4030</b>		
Kubota 5-Cyl. 148 Diesel		
1998–1986		
Belt - Fan & Alt. ....	15196-97010	▲9430HD
<b>Kubota 6-Cyl. 159 Diesel</b>		
1994–1986		
Belt - Fan & Alt. ....		▲9430HD
Hose - Upper .....		◊<20137
		or ●25252
Hose - Lower; W/Single Hose .....		◊<21103
Hose - Lower - Eng. To Pipe .....		◊<21942
Hose - Lower - Pipe To Rad. ....		24222
<b>M4050</b>		
Kubota 6-Cyl. 159 Diesel		
1988–1982		
Belt - Fan & Alt. ....		▲9440HD
<b>M4500</b>		
Kubota 6-Cyl. 159 Diesel		
1986–1978		
Belt - Fan & Alt. ....	15606-97012	▲9435HD
<b>M4700</b>		
Kubota 5-Cyl. 168 Diesel		
1999–1995		
Belt - Fan & Alt. ....		▲9430HD

②Two Required ◊<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Agricultural Equipment





Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>M4800</b>		
<b>Kubota 4-Cyl. 149 Diesel</b>		
2010-2009		
Belt - Fan .....	15471-97010	▲9420HD
2008-2003		
Belt - Alt. ....	15469-97010	▲9425HD
Belt - Fan .....	15471-97010	▲9420HD
<b>M4900</b>		
<b>Kubota 5-Cyl. 168 Diesel</b>		
2008-2002		
Belt - Fan .....	15196-97010	▲9430HD
2001		
Belt - Alt. ....		▲9430HD
2000		
Belt - Fan .....	15196-97010	▲9430HD
<b>M4950</b>		
<b>Kubota 6-Cyl. 170 Diesel</b>		
1995-1983		
Belt - Fan & Alt. ....		▲9435HD
Hose - Upper .....		≠20137
		or ●25252
Hose - Lower - Eng. To Pipe .....		≠20065
Hose - Lower - Pipe To Rad. ....		24224
<b>M5030</b>		
<b>Kubota 6-Cyl. 170 Diesel</b>		
1996-1985		
Belt - A.C. ....		A53
Belt - Fan & Alt. ....		▲9430HD
Hose - Upper .....		≠20137
		or ●25252
Hose - Lower .....		≠20661
		or ●25251
<b>M5040</b>		
<b>Kubota 4-Cyl. 186 Diesel</b>		
2008-2006		
Belt - Alt. ....		▲9360HD
Belt - Fan .....		▲9447HD
<b>M5400</b>		
<b>Kubota 5-Cyl. 168 Diesel</b>		
1999-1994		
Belt - Fan & Alt. ....		▲9430HD
<b>M5500</b>		
<b>Kubota 3-Cyl. 182 Diesel</b>		
1986-1979		
Belt - Fan & Alt. ....		②▲9435HD
<b>M5700</b>		
<b>Kubota 5-Cyl. 168 Diesel</b>		
2008-2000		
Belt - Alt. ....		▲9430HD
<b>M5950</b>		
<b>Kubota 3-Cyl. 196 Diesel</b>		
1994-1983		
Belt - A.C.; W/1/2" Belt T.W. ....		▲9650HD
Belt - A.C.; W/21/32" Belt T.W. ....		TR22635
Belt - Fan & Alt. ....		②7460
<b>M6030</b>		
<b>Kubota 3-Cyl. 196 Diesel</b>		
1998-1986		
Belt - A.C.; W/1/2" Belt T.W. ....		▲9650HD
Belt - A.C.; W/21/32" Belt T.W. ....		TR22635
Belt - Fan & Alt. ....		②7460
Hose - Lower .....		≠20957

Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>M6800</b>		
<b>Kubota 4-Cyl. 202 Diesel</b>		
2008-1998		
Belt - Alt. ....		▲9480HD
<b>M6950</b>		
<b>Kubota 4-Cyl. 243 Diesel</b>		
1996-1983		
Belt - A.C.; W/1/2" Belt T.W. ....		▲9650HD
Belt - A.C.; W/21/32" Belt T.W. ....		TR22635
Belt - Fan & Alt. ....		②7460
<b>M7030</b>		
<b>Kubota 4-Cyl. 243 Diesel</b>		
1998-1986		
Belt - A.C.; W/1/2" Belt T.W. ....		▲9650HD
Belt - A.C.; W/21/32" Belt T.W. ....		TR22635
Belt - Fan & Alt. ....		②7460
Hose - Lower .....		≠21660
		or ●25477
<b>M7040</b>		
<b>Kubota 4-Cyl. 203 Diesel</b>		
2008-2006		
Belt - Alt. ....		▲9360HD
Belt - Fan .....		▲9447HD
<b>M7500</b>		
<b>Kubota 4-Cyl. 243 Diesel</b>		
1986-1979		
Belt - Fan & Alt. ....		②▲9435HD
<b>M7580</b>		
<b>Kubota V4302A Diesel</b>		
1999-1992		
Belt - Fan & Alt. ....	1545199380	7450
<b>M7950</b>		
<b>Kubota 4-Cyl. 262 Diesel</b>		
1996-1983		
Belt - A.C.; W/1/2" Belt T.W. ....		▲9650HD
Belt - A.C.; W/21/32" Belt T.W. ....		TR22635
Belt - Fan & Alt.; W/45 5/8" Belt O.C. ....		②7450
Belt - Fan & Alt.; W/46 5/8" Belt O.C. ....		②7460
Hose - Lower .....		≠21660
		or ●25477
<b>M8030</b>		
<b>Kubota 4-Cyl. 262 Diesel</b>		
1997-1986		
Belt - A.C.; W/1/2" Belt T.W. ....		▲9650HD
Belt - A.C.; W/21/32" Belt T.W. ....		TR22635
Belt - Fan & Alt. ....		②7460
Hose - Lower .....		≠21660
		or ●25477
<b>M8200</b>		
<b>Kubota 4-Cyl. 202 Diesel</b>		
2008-1998		
Belt - Fan & Alt. ....	490	▲9500HD
<b>M8540</b>		
<b>Kubota 4-Cyl. 230 Diesel</b>		
2008-2006		
Belt - Alt. ....		▲9495HD
<b>M8580</b>		
<b>Kubota V4702A Diesel</b>		
1999-1991		
Belt - A.C.; W/1/2" Belt T.W. ....		▲9650HD
Belt - A.C.; W/21/32" Belt T.W. ....		TR22635
Belt - Fan & Alt. ....		②7460
Hose - Upper .....		●26603

②Two Required ≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>KUBOTA - Continued</b>		
<b>M8580 – Continued</b>		
Kubota V4702A Diesel – Continued		
1999–1991 – Continued		
Hose - Lower .....		●25477
<b>M8950</b>		
Kubota 4–Cyl. 262 Diesel		
1996–1983		
Belt - A.C.; W/1/2" Belt T.W. ....		▲9650HD
Belt - A.C.; W/21/32" Belt T.W. ....		TR22635
Belt - Fan & Alt. ....		②7460
Hose - Upper .....		●26510
Hose - Lower .....		③<21660
	or	●25477
<b>M9000</b>		
Kubota 4–Cyl. 202 Diesel		
2008–1998		
Belt - Alt. ....		▲9610HD
<b>M9540</b>		
Kubota 4–Cyl. 230 Diesel		
2008–2006		
Belt - Fan & Alt. ....		▲9495HD
<b>M9580</b>		
Kubota V4702TA Diesel		
1998–1992		
Belt - A.C. ....		▲9650HD
Belt - Fan & Alt. ....		②7450
Hose - Upper .....		③<20957
Hose - Lower .....		③<21660
<b>MX4700</b>		
Kubota 4–Cyl. 149 Diesel		
2014–2009		
Belt - Fan .....	15469-97010	▲9425HD
<b>MX5000</b>		
Kubota 4–Cyl. 149 Diesel		
2007–2002		
Belt - Alt. ....	15471-97010	▲9420HD
<b>MX5100</b>		
Kubota 4–Cyl. 149 Diesel		
2014–2008		
Belt - Fan .....	15469-97010	▲9425HD
<b>LANDINI</b>		
<b>5560</b>		
Perkins 3–Cyl. 152 Diesel		
1994–1988		
Belt - Fan & Alt. ....		▲9465HD
<b>6530</b>		
Perkins 4–Cyl. 236 Diesel		
1991–1985		
Belt - Fan & Alt. ....	1446980M1	▲9476HD
Hose - Upper .....		24228
<b>6830</b>		
Perkins 4–Cyl. 236 Diesel		
1988–1984		
Belt - Fan & Alt. ....		②▲9480HD
Hose - Upper .....		24428

Application	OEM No.	Our No.
<b>LANDINI - Continued</b>		
<b>7830</b>		
Perkins 4–Cyl. 236 Diesel		
1991–1984		
Belt - Fan & Alt. ....	2614B542	7465
<b>7860</b>		
Perkins 4–Cyl. 236 Diesel		
1996–1988		
Belt - Fan & Alt. ....		▲9470HD
<b>8550</b>		
Perkins 4–Cyl. 248 Diesel		
1988–1985		
Belt - A.C. ....		▲9700HD
Belt - Fan & Alt. ....	1446201M1	▲9505HD
Hose - Upper .....		③<20957
<b>8560</b>		
Perkins 4–Cyl. 248 Diesel		
1994–1990		
Belt - Fan & Alt. ....		▲9480HD
<b>10000S</b>		
Perkins 6–Cyl. 354 Diesel		
1996–1982		
Belt - Fan & Alt.; Ser. No. 12900075 & Before .....	1447695M91	②▲9580HD
Belt - Fan & Alt.; Ser. No. 12900076 & After .....		②▲9590HD
<b>12500</b>		
Perkins 6–Cyl. 354 Diesel		
1991–1985		
Belt - Fan & Alt. ....		②▲9600HD
<b>14500</b>		
Perkins 6–Cyl. 354 Diesel		
1996–1986		
Belt - Fan & Alt.; Ser. No. U536462 & Before .....		②▲9610HD
Belt - Fan & Alt.; Ser. No. U536463 & After ..	1447419M91	②▲9600HD
Hose - By Pass .....		24236
<b>CF5030</b>		
Perkins AD3.1525 Diesel		
1994–1991		
Belt - Fan & Alt. ....		▲9465HD
Hose - Upper .....		24226
Hose - By Pass .....		③<21942
<b>DT5500</b>		
Perkins 3–Cyl. 152 Diesel		
1988		
Belt - Fan & Alt. ....	1446203M1	▲9490HD
<b>DT6500</b>		
Perkins 4–Cyl. 236 Diesel		
1988		
Belt - Fan & Alt.; Ser. No. 1214499 & Before .....	1447592M1	▲9470HD
Belt - Fan & Alt.; Ser. No. 1214500 & After ..	1446980M1	▲9476HD
<b>DT8500</b>		
Perkins 4–Cyl. 248 Diesel		
1988		
Belt - Fan & Alt.; Ser. No. 1231517 & Before .....	1447592M1	▲9470HD
Belt - Fan & Alt.; Ser. No. 1231518 & After ..	1446980M1	▲9476HD
<b>Trekker 85</b>		
Perkins 4–Cyl. 248 Diesel		
2000–1992		
Belt - Fan & Alt. ....		▲9470HD
Hose - Upper .....		24228

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>LEYLAND</b>		
<b>154</b>		
<b>Leyland 4-Cyl. 91 Diesel</b>		
1984-1979		
Belt - Fan & Alt.; W/40 1/4" Belt O.C. ....	13H3348	▲9400HD
Belt - Fan & Alt.; W/41 3/4" Belt O.C. ....		▲9415HD
Belt - Hyd. Pump .....	BTJ6280	TR22525
<b>Leyland 4-Cyl. 99</b>		
1984-1970		
Belt - Fan & Alt. ....	13H4646	▲9380HD
Belt - Hyd. Pump .....	BTJ6280	TR22525
<b>235</b>		
<b>Leyland 4-Cyl. 109 Diesel</b>		
1984-1982		
Belt - Hyd. Pump .....		▲9510HD
<b>245</b>		
<b>Perkins 3-Cyl. 152 Diesel</b>		
1984-1973		
Belt - Fan & Alt. ....	12B633	TR22461
<b>253</b>		
<b>Perkins 3-Cyl. 152 Diesel</b>		
1972		
Belt - Fan & Alt. ....	12B633	TR22461
<b>272</b>		
<b>Leyland 4-Cyl. 230 Diesel</b>		
1984-1976		
Belt - Fan & Alt. ....	12B1421	▲9505HD
<b>344</b>		
<b>Leyland 4-Cyl. 208 Diesel</b>		
1972-1970		
Belt - Fan & Alt. ....	BMK977	▲9510HD
Hose - Upper .....		≧20450
		or ●25474
Hose - Lower .....		24224
<b>384</b>		
<b>Leyland 4-Cyl. 230 Diesel</b>		
1972-1970		
Belt - Fan & Alt. ....	12B1421	▲9505HD
Hose - Upper .....		≧20450
		or ●25474
Hose - Lower .....		24224
<b>LONG</b>		
<b>260</b>		
<b>UTB 2-Cyl. 95 Diesel</b>		
1986-1980		
Belt - Fan & Alt. ....		7455
Hose - Upper .....		●26602
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>310</b>		
<b>UTB 2-Cyl. 110 Diesel</b>		
1990-1980		
Belt - Fan & Alt. ....		7455
Hose - Upper .....		●26602
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>350</b>		
<b>UTB 3-Cyl. 143 Diesel</b>		
1976-1974		
Belt - Fan & Alt. ....		7450
Hose - Upper .....		●26603
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224

Application	OEM No.	Our No.
<b>LONG - Continued</b>		
<b>360</b>		
<b>UTB 3-Cyl. 143 Diesel</b>		
1994-1977		
Belt - Fan & Alt. ....		7450
Hose - Upper - Eng. To Pipe .....		24230
Hose - Upper - Pipe To Rad. ....		24230
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>445</b>		
<b>UTB 3-Cyl. 143 Diesel</b>		
1976-1972		
Belt - Fan & Alt. ....		7450
Hose - Upper .....		≧20957
		or ●26603
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>460</b>		
<b>UTB 3-Cyl. 143 Diesel</b>		
1994-1977		
Belt - Fan & Alt. ....		7450
Hose - Upper - Eng. To Pipe .....		24230
Hose - Upper - Pipe To Rad. ....		24230
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>510</b>		
<b>UTB 3-Cyl. 165 Diesel</b>		
1990-1979		
Belt - Fan & Alt. ....		7450
Hose - Upper .....		≧20958
		or ●26502
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>560</b>		
<b>UTB 4-Cyl. 191 Diesel</b>		
1979-1976		
Belt - Fan & Alt.; W/45 1/8" Belt O.C. ....		7450
Belt - Fan & Alt.; W/55 5/8" Belt O.C. ....		7555
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
Hose - By Pass .....		≧20782
<b>610</b>		
<b>UTB 4-Cyl. 219 Diesel</b>		
1994-1979		
Belt - Fan & Alt. ....		7450
Hose - Upper .....		≧20958
		or ●26502
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>900</b>		
<b>Zetor 4-Cyl. 278 Diesel</b>		
1977-1974		
Belt - Fan & Alt. ....		▲9505HD
Hose - Upper .....		●26504
Hose - Lower - Eng. To Pipe .....		≧20065
		or ●25526
Hose - Lower - Pipe To Rad. ....		24224
<b>910</b>		
<b>Zetor 4-Cyl. 278 Diesel</b>		
1983-1978		
Belt - Fan & Alt. ....		▲9505HD
Hose - Lower - Pipe To Rad. ....		24224
<b>1100</b>		
<b>Zetor 4-Cyl. 278 Diesel</b>		
1977-1975		
Belt - A.C. ....		▲9505HD
Belt - Fan & Alt. ....		7512

≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>LONG - Continued</b>		
<b>1100 - Continued</b>		
<b>Zetor 4-Cyl. 278 Diesel - Continued</b>		
1977-1975 - Continued		
Hose - Upper .....		●25527
Hose - Lower - Pipe To Rad. ....		24224
<b>1110</b>		
<b>Zetor 4-Cyl. 278 Diesel</b>		
1979-1978		
Belt - A.C. ....		▲9463HD
Belt - Fan & Alt. ....		▲9510HD
<b>1310</b>		
<b>Zetor 6-Cyl. 417 Diesel</b>		
1983-1978		
Belt - A.C. ....		▲9463HD
Belt - Fan & Alt. ....		▲9510HD
<b>FarmTrac 45</b>		
<b>Ford 3-Cyl. 175 Diesel</b>		
2000-1999		
Belt - Fan & Alt. ....	1405	7405
<b>FarmTrac 60</b>		
<b>Ford 3-Cyl. 192 Diesel</b>		
2003-1997		
Belt - Fan & Alt. ....	1405	7405
<b>LandTrac 280</b>		
<b>Mitsubishi 4-Cyl. 92 Diesel</b>		
2000-1998		
Belt - Fan & Alt. ....	MD041704	7380
<b>LandTrac 360</b>		
<b>Mitsubishi 4-Cyl. 107 Diesel</b>		
2003-1998		
Belt - Fan & Alt. ....	MD041704	7380
<b>R9500</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1975-1972		
Belt - Fan & Alt. ....		▲9590HD
Hose - Upper .....		⊗<20611
		or ●26508
Hose - Lower - Eng. To Pipe .....		⊗<20882
Hose - Lower - Pipe To Rad. ....		⊗<20685
<b>MAHINDRA</b>		
<b>475</b>		
<b>Mahindra 3-Cyl. 115 Diesel</b>		
1999-1997		
Belt - Alt. ....	5556085R1	AX31
Belt - Fan .....	5554153R1	TR22358
<b>485</b>		
<b>Mahindra 4-Cyl. 146 Diesel</b>		
1997		
Belt - Alt. ....	5556085R1	AX31
Belt - Fan .....	5554153R1	TR22358
<b>575</b>		
<b>Mahindra 4-Cyl. 154 Diesel</b>		
1998-1996		
Belt - Alt. ....	5556085R1	AX31
Belt - Fan .....	5554153R1	TR22358

Application	OEM No.	Our No.
<b>MAHINDRA - Continued</b>		
<b>2516</b>		
<b>Mahindra 3-Cyl. 80 Diesel</b>		
2013-2008		
Belt - Fan .....	MD025523	7375
<b>2615</b>		
<b>Mahindra 3-Cyl. 80 Diesel</b>		
2010-2005		
Belt - Fan .....	MD041704	7380
<b>2815</b>		
<b>Mahindra 3-Cyl. 91 Diesel</b>		
2008-2005		
Belt - Fan .....		▲9370HD
<b>2816</b>		
<b>Mahindra 3-Cyl. 80 Diesel</b>		
2010-2008		
Belt - Fan .....	MD041704	7380
<b>3015</b>		
<b>Mahindra 3-Cyl. 91 Diesel</b>		
2009-2005		
Belt - Fan .....	MD041704	7380
<b>3016</b>		
<b>Mahindra 3-Cyl. 80 Diesel</b>		
2015-2009		
Belt - Fan .....	MD041704	7380
<b>3215</b>		
<b>Mahindra 3-Cyl. 91 Diesel</b>		
2007-2005		
Belt - Fan .....		▲9370HD
<b>3505</b>		
<b>Mahindra 3-Cyl. 115 Diesel</b>		
2003-2000		
Belt - Alt. ....	5556085R1	AX31
<b>3510</b>		
<b>Mahindra 3-Cyl. 100 Diesel</b>		
2010-2000		
Belt - Fan .....	E5800-72531	▲9425HD
<b>4005</b>		
<b>Mahindra 4-Cyl. 146 Diesel</b>		
1999-1998		
Belt - Alt. ....	5556085R1	AX31
<b>4010</b>		
<b>Mahindra 3-Cyl. 111 Diesel</b>		
2015-2011		
Belt - Fan .....	E5800-72531	▲9425HD
<b>4500</b>		
<b>Mahindra 3-Cyl. 146 Diesel</b>		
2005-2000		
Belt - Fan & Alt. ....	20325E05	▲9455HD
<b>4505</b>		
<b>Mahindra 4-Cyl. 154 Diesel</b>		
1999-1998		
Belt - Alt. ....	5556085R1	AX31
<b>4510</b>		
<b>Mahindra 4-Cyl. 134 Diesel</b>		
2010-2004		
Belt - Fan .....	E5800-72531	▲9425HD

⊗<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MAHINDRA - Continued</b>		
<b>4530</b>		
<b>Mahindra 3-Cyl. 146 Diesel</b>		
2008-2005		
Belt - Fan & Alt. ....	20325E05	▲9455HD
<b>5005</b>		
<b>Mahindra 4-Cyl. 154 Diesel</b>		
1999-1998		
Belt - Alt. ....	5556085R1	AX31
<b>5010</b>		
<b>Mahindra 4-Cyl. 149 Diesel</b>		
2015-2009		
Belt - Fan ....	E5800-72531	▲9425HD
<b>5500</b>		
<b>Mahindra 4-Cyl. 186 Diesel</b>		
2007-2003		
Belt - Fan & Alt. ....	20325E05	▲9455HD
<b>6000</b>		
<b>Mahindra 4-Cyl. 195 Diesel</b>		
2007-1999		
Belt - Fan & Alt. ....	20325E05	▲9455HD
<b>6500</b>		
<b>Mahindra 4-Cyl. 216 Diesel</b>		
2007-2003		
Belt - Fan & Alt. ....	20325E05	▲9455HD
<b>C27; C35</b>		
<b>Mahindra 3-Cyl. 115 Diesel</b>		
2003		
Belt - Alt. ....	5556085R1	AX31
<b>E350</b>		
<b>Mahindra 3-Cyl. 115 Diesel</b>		
2003-2000		
Belt - Alt. ....	5556085R1	AX31
<b>MASSEY FERGUSON</b>		
<b>20 Industrial</b>		
<b>Perkins 3-Cyl. 152</b>		
1976-1966		
Belt - Fan & Alt. ....	517456M1	▲9500HD
Hose - Upper .....		24224
Hose - Lower .....		●25476
Hose - By Pass .....		24218
<b>Perkins 3-Cyl. 153 Diesel</b>		
1976-1966		
Belt - Fan & Alt. ....	517456M1	▲9500HD
Hose - Upper .....		24224
Hose - Lower .....		≧20226
		or ●25477
Hose - By Pass .....		24218
<b>20C Industrial</b>		
<b>Perkins 3-Cyl. 152</b>		
1982-1976		
Belt - Fan & Alt. ....	539735M1	▲9435HD
<b>Perkins 3-Cyl. 153 Diesel</b>		
1982-1976		
Belt - Fan & Alt. ....	531371M1	▲9525HD

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>20C Turf</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1976-1975		
Belt - Fan & Alt. ....	843198M1	▲9525HD
<b>20D Industrial</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1992-1983		
Belt - Fan & Alt. ....	1682680M1	▲9510HD
Hose - Upper .....		24224
Hose - Lower .....		≧21794
		or ●25476
Hose - By Pass .....		24218
<b>25</b>		
<b>Perkins 4-Cyl. 107 Diesel</b>		
1965-1963		
Belt - Fan & Alt. ....	966427M1	▲9390HD
Hose - Upper .....		24224
<b>30</b>		
<b>Continental 4-Cyl. 212</b>		
1976-1970		
Belt - Fan & Alt. ....	843198M1	▲9525HD
Hose - Upper .....		24224
<b>Perkins 4-Cyl. 203 Diesel</b>		
1976-1970		
Belt - Fan & Alt. ....	186976M1	▲9490HD
Hose - Upper .....		24224
<b>30 Industrial</b>		
<b>Perkins 4-Cyl. 203</b>		
1972-1970		
Hose - Upper .....		●25476
Hose - Lower .....		≧20945
		or ●25474
<b>Perkins 4-Cyl. 212 Diesel</b>		
1972-1970		
Belt - Fan & Alt. ....	531371M1	▲9525HD
Hose - Upper .....		≧20065
		or ●25473
Hose - By Pass .....		24216
<b>30B Industrial</b>		
<b>Continental 4-Cyl. 162</b>		
1982-1976		
Belt - Fan & Alt. ....	539735M1	▲9435HD
Hose - Upper .....		●25476
Hose - Lower .....		≧20945
		or ●25474
<b>Perkins 4-Cyl. 212 Diesel</b>		
1982-1976		
Belt - Fan & Alt. ....	531371M1	▲9525HD
Hose - Upper .....		≧20065
		or ●25473
Hose - By Pass .....		24216
<b>31 Industrial</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1977-1973		
Belt - Fan & Alt. ....	513833M1	▲9520HD
<b>35</b>		
<b>Continental 4-Cyl. 134</b>		
1963-1960		
Belt - Fan & Alt./Gen. ....	509572M1	▲9425HD
Hose - Upper .....		24224
Hose - Lower .....		≧20416
		or ●25477

≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>35 - Continued</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1963-1960		
Belt - Fan & Alt./Gen. ....	186976M1	▲9490HD
Hose - Upper .....		24224
Hose - Lower .....		☉20226
		or ●25477
Hose - By Pass .....		24218
<b>40</b>		
<b>Continental 4-Cyl. 134</b>		
1984-1956		
Belt - Fan & Alt. ....	517456M1	▲9500HD
Hose - Upper .....		●25476
<b>Perkins 3-Cyl. 153 Diesel</b>		
1984-1956		
Belt - Fan & Alt. ....	517456M1	▲9500HD
Hose - Upper .....		●25473
Hose - By Pass .....		☉20801
<b>40B Industrial</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1982-1976		
Belt - Fan & Alt. ....	517344M2	▲9540HD
<b>50</b>		
<b>Continental 4-Cyl. 134</b>		
1965-1958		
Belt - Fan & Alt. ....	513890M1	▲9451HD
Belt - Fan & Gen. ....	509572M1	▲9425HD
Hose - Upper .....		24224
Hose - Lower .....		●25478
<b>Perkins 3-Cyl. 153 Diesel</b>		
1965-1958		
Belt - Fan & Alt./Gen. ....	189789M1	▲9485HD
Hose - Upper .....		24224
Hose - By Pass .....		24218
<b>50 Industrial</b>		
<b>Continental 4-Cyl. 193</b>		
1976-1969		
Belt - Fan & Alt. ....	513890M1	▲9451HD
Belt - Fan & Gen. ....	509572M1	▲9425HD
<b>Perkins 4-Cyl. 203 Diesel</b>		
1976-1969		
Belt - Fan & Alt. ....	843198M1	▲9525HD
Belt - Fan & Gen. ....	186750M2	▲9476HD
<b>50C Industrial; 50D Industrial</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1983-1976		
Belt - Fan & Alt. ....	517344M2	▲9540HD
<b>50F</b>		
<b>Perkins 3-Cyl. 184 Diesel</b>		
1987-1983		
Belt - Fan & Alt. ....	1446201M1	▲9505HD
<b>65</b>		
<b>Continental 4-Cyl. 176</b>		
1965-1957		
Belt - Fan & Alt./Gen. ....	184526M1	▲9440HD
Hose - Upper .....		24224
Hose - Lower .....		●25478
<b>Perkins 4-Cyl. 203 Diesel</b>		
1965-1957		
Belt - Fan & Alt./Gen. ....	186750M2	▲9476HD
Hose - Upper .....		●25527
Hose - Lower .....		●25478
Hose - By Pass - W.P. To Intake Manifold .....		24216

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>65 - Continued</b>		
<b>Perkins 4-Cyl. 203 Diesel - Continued</b>		
1965-1957 - Continued		
Hose - By Pass - W.P. To Pipe .....		☉20267
<b>85</b>		
<b>Continental 4-Cyl. 242</b>		
1962-1958		
Belt - Fan & Gen. ....	185223M1	▲9530HD
Hose - Upper .....		24226
Hose - Lower .....		☉21794
		or ●25476
<b>Perkins 4-Cyl. 242 Diesel</b>		
1961-1958		
Belt - Fan & Gen. ....	190083M1	▲9510HD
Hose - Upper .....		24926
<b>88</b>		
<b>Continental 4-Cyl. 276</b>		
1962-1959		
Belt - Fan & Gen. ....	185223M1	▲9530HD
Hose - Upper .....		24226
Hose - Lower .....		☉21794
		or ●25476
<b>Perkins 4-Cyl. 277 Diesel</b>		
1962-1959		
Belt - Fan & Gen. ....	190083M1	▲9510HD
Hose - Upper .....		24926
<b>90</b>		
<b>Continental 4-Cyl. 242</b>		
1965-1962		
Belt - Fan & Gen. ....	185223M1	▲9530HD
Hose - Upper .....		24226
<b>Perkins 4-Cyl. 302 Diesel</b>		
1965-1962		
Belt - Fan & Gen. ....	190083M1	▲9510HD
Hose - Upper .....		24926
Hose - Lower .....		☉21794
		or ●25480
Hose - By Pass .....		☉20267
<b>135</b>		
<b>Continental 4-Cyl. 145</b>		
1975-1964		
Belt - Fan & Gen. ....	509572M1	▲9425HD
Hose - Upper .....		●25472
Hose - Lower .....		☉20416
		or ●25473
<b>Perkins 3-Cyl. 152</b>		
1975-1969		
Belt - Fan & Gen. ....	509572M1	▲9425HD
Hose - Upper .....		●25472
Hose - Lower .....		☉20416
		or ●25473
<b>Perkins 3-Cyl. 152 Diesel</b>		
1975-1964		
Belt - Fan & Alt.; Special; Ser. No. 9A38905 & After .....	843198M1	▲9525HD
Belt - Fan & Alt.; W/Orchard Style; Ser. No. 9A38905 & After .....	517456M1	▲9500HD
Belt - Fan & Gen.; Ser. No. 9A38904 & Before .....	186976M1	▲9490HD
Hose - Upper .....		24224
Hose - Lower .....		☉20226
		or ●25476
Hose - By Pass; Molded Hose .....		☉20801
Hose - By Pass; Strt. Hose .....		24218

☉Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>150</b>		
<b>Continental 4-Cyl. 145</b>		
1975-1964		
Belt - Fan & Gen. ....	509572M1	▲9425HD
Hose - Upper .....		✂20416
		or ●25474
Hose - Lower .....		●25478
<b>Continental 4-Cyl. 152</b>		
1975-1964		
Belt - Fan & Gen. ....	509572M1	▲9425HD
Hose - Upper .....		✂20416
		or ●25474
Hose - Lower .....		●25478
<b>Perkins 3-Cyl. 153 Diesel</b>		
1975-1964		
Belt - Fan & Alt. ....	517344M1	▲9540HD
Belt - Fan & Gen. ....	186976M1	▲9490HD
Hose - Upper .....		✂21794
		or ●25474
Hose - Lower .....		●25478
Hose - By Pass; Molded Hose .....		✂20801
Hose - By Pass; Strt. Hose .....		24218
<b>154-4</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1981-1980		
Belt - Fan & Alt.; Ser. No. 2612418 & After ..	1446203M1	▲9490HD
<b>165</b>		
<b>Continental 4-Cyl. 176</b>		
1975-1964		
Belt - Fan & Gen. ....	189789M1	▲9485HD
Hose - Upper; W/Row Crop Style .....		✂20065
		or ●25473
Hose - Upper; W/Tricycle Style .....		●25476
Hose - Lower; W/Row Crop Style .....		●25473
Hose - Lower; W/Tricycle Style .....		●25474
<b>Perkins 4-Cyl. 204 Diesel</b>		
1975-1964		
Belt - Fan & Alt. ....	186976M1	▲9490HD
Belt - Fan & Gen. ....	186750M2	▲9476HD
Hose - Upper; W/Row Crop Style .....		✂20065
Hose - Upper; W/Tricycle Style .....		✂21660
		or ●25476
Hose - Lower; W/Row Crop Style .....		20355
		or ●25476
Hose - By Pass; Molded Hose .....		✂20267
Hose - By Pass; Strt. Hose .....		24216
<b>Perkins 4-Cyl. 212</b>		
1975-1964		
Belt - Fan & Gen. ....	189789M1	▲9485HD
Hose - Upper; W/Row Crop Style .....		✂20065
		or ●25473
Hose - Upper; W/Tricycle Style .....		●25476
Hose - Lower; W/Row Crop Style .....		●25473
Hose - Lower; W/Tricycle Style .....		●25474
<b>175</b>		
<b>Continental 4-Cyl. 206</b>		
1975-1964		
Belt - Fan & Gen. ....	189789M1	▲9485HD
Hose - Upper .....		✂20065
		or ●25473
Hose - Lower .....		●25473
<b>Perkins 4-Cyl. 236</b>		
1975-1964		
Belt - Fan & Alt. ....	843198M1	▲9525HD
Hose - Upper .....		✂20355
		or ●25474
Hose - Lower; Ser. No. 9A67214 & Before .....		✂21794
		or ●25476
Hose - Lower; Ser. No. 9A67215 & After .....		●25473

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>175 - Continued</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1975-1964		
Belt - Fan & Alt. ....	513833M1	▲9520HD
Belt - Fan & Gen.; Ser. No. 9A40276 & Before .....	186750M2	▲9476HD
Belt - Fan & Gen.; Ser. No. 9A40277 & After .....	190083M1	▲9510HD
Hose - Upper .....		20355
		or ●25474
Hose - Lower; W/1 1/2" O.D. Rad. Spout .....		✂20993
		or ●25476
Hose - Lower; W/1 3/4" O.D. Rad. Spout .....		✂20558
		or ●26502
<b>180</b>		
<b>Continental 4-Cyl. 206</b>		
1975-1964		
Belt - Fan & Gen. ....	505995M2	▲9447HD
Hose - Upper .....		✂20626
		or ●25480
<b>Perkins 4-Cyl. 236</b>		
1975-1965		
Belt - Fan & Gen. ....	186976M1	▲9490HD
Hose - Upper .....		✂20626
		or ●25480
<b>Perkins 4-Cyl. 236 Diesel</b>		
1975-1964		
Belt - Fan & Gen.; Ser. No. 9A40276 & Before .....	186750M2	▲9476HD
Belt - Fan & Gen.; Ser. No. 9A40277 & After .....	512951M1	▲9500HD
Hose - Upper; W/1 1/2" O.D. Rad. Spout .....		✂20626
		or ●25480
Hose - Upper; W/1 3/4" O.D. Rad. Spout .....		●26612
<b>184-4</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1981-1976		
Belt - Fan & Gen. ....	1446980M1	▲9476HD
<b>202 Industrial</b>		
<b>Continental Z134</b>		
1967-1958		
Belt - Fan & Alt. ....	509572M1	▲9425HD
<b>Perkins 3-Cyl. 152 Diesel</b>		
1967-1958		
Belt - Fan & Alt. ....	509572M1	▲9425HD
<b>203 Industrial</b>		
<b>Perkins 3-Cyl. 152 Diesel</b>		
1967-1961		
Belt - Fan & Alt. ....	186976M1	▲9490HD
<b>204 Industrial</b>		
<b>Perkins 3-Cyl. 152 Diesel</b>		
1967-1959		
Belt - Fan & Alt. ....	509572M1	▲9425HD
<b>205</b>		
<b>Toyosha 2-Cyl. 65 Diesel</b>		
1984-1978		
Belt - Fan & Gen. ....	3281495M1	▲9370HD
Hose - Lower .....		●25252

✂Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>205 Industrial</b>		
<b>Toyosha 2-Cyl. 65 Diesel</b>		
1969-1961		
Belt - Fan & Gen. ....	186976M1	▲9490HD
<b>205-4</b>		
<b>Toyosha 2-Cyl. 65 Diesel</b>		
1984-1979		
Belt - Fan & Gen. ....	3281495M1	▲9370HD
Hose - Lower .....		●25252
1978		
Belt - Fan & Alt. ....	3280157M1	▲9400HD
Belt - Fan & Gen. ....	3281495M1	▲9370HD
Hose - Upper .....		☞<20065
	or	●25472
Hose - Lower .....		●25252
<b>210</b>		
<b>Toyosha 2-Cyl. 77 Diesel</b>		
1984-1978		
Belt - Fan & Alt. ....	3280157M1	▲9400HD
Hose - Upper .....		☞<20065
	or	●25472
Hose - Lower .....		☞<21794
	or	●25476
<b>210-4</b>		
<b>Toyosha 2-Cyl. 77 Diesel</b>		
1984-1979		
Belt - Fan & Alt. ....	3280157M1	▲9400HD
Hose - Upper .....		☞<20065
	or	●25472
Hose - Lower .....		☞<21794
	or	●25476
<b>220; 220-4</b>		
<b>Toyosha 2-Cyl. 90 Diesel</b>		
1984-1978		
Belt - Fan & Alt. ....	3280157M1	▲9400HD
<b>230</b>		
<b>Continental 4-Cyl. 145</b>		
1983-1976		
Belt - Fan & Alt. ....	539735M1	▲9435HD
Hose - Upper; Ser. No. 9A243082 & After .....		●25473
<b>Perkins 3-Cyl. 153 Diesel</b>		
1983-1976		
Belt - Fan & Alt. ....	531371M1	▲9525HD
Hose - Upper .....		●25473
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		☞<20267
<b>231 Special</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1999-1989		
Belt - Fan & Alt.; W/45 3/8" Belt O.C. ....		▲9451HD
Belt - Fan & Alt.; W/47 3/8" Belt O.C. ....	773300M1	▲9470HD
Hose - Lower .....		☞<21660
<b>235</b>		
<b>Continental 4-Cyl. 145</b>		
1976-1975		
Belt - Fan & Alt. ....	539735M1	▲9435HD
Hose - Upper; Ser. No. 9A243082 & After .....		●25473
<b>Perkins 3-Cyl. 153 Diesel</b>		
1976-1975		
Belt - Fan & Alt. ....	531371M1	▲9525HD
Hose - Upper .....		●25473
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		☞<20267

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>240</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1999-1983		
Belt - Fan & Alt. ....	1682680M1	▲9510HD
Hose - Upper .....		24224
Hose - Lower .....		●25477
<b>245</b>		
<b>Continental 4-Cyl. 145</b>		
1983-1976		
Belt - Fan & Alt. ....	539735M1	▲9435HD
Hose - Lower .....		☞<20267
<b>Perkins 3-Cyl. 153 Diesel</b>		
1983-1976		
Belt - Fan & Alt. ....	531371M1	▲9525HD
Hose - Upper .....		☞<20065
	or	●25526
Hose - Lower .....		20355
	or	●25477
Hose - By Pass; Molded Hose .....		☞<20267
Hose - By Pass; Strt. Hose .....		24218
<b>250</b>		
<b>Perkins 3-Cyl. 152 Diesel</b>		
1986-1983		
Belt - Fan & Alt. ....	1682680M1	▲9510HD
Hose - Upper .....		24224
Hose - Lower .....		●25477
<b>253</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1998-1988		
Belt - Fan & Alt. ....		▲9463HD
Hose - Upper .....		24224
Hose - By Pass .....		24220
<b>254</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1987-1982		
Belt - Fan & Alt. ....	1446203M1	▲9490HD
Hose - Upper .....		24228
Hose - By Pass .....		24218
<b>255</b>		
<b>Continental 4-Cyl. 212</b>		
1982-1975		
Belt - Fan & Alt. ....	531371M1	▲9525HD
Hose - Lower .....		☞<20945
	or	●25474
<b>Perkins 4-Cyl. 203 Diesel</b>		
1982-1975		
Belt - Fan & Alt. ....	532527M1	▲9490HD
<b>Perkins 4-Cyl. 236 Diesel</b>		
1982-1975		
Belt - Fan & Alt. ....	517344M2	▲9540HD
<b>265</b>		
<b>Continental 4-Cyl. 236</b>		
1983-1975		
Hose - Upper .....		☞<20355
	or	●25477
Hose - Lower .....		☞<20945
	or	●25474
<b>Perkins 4-Cyl. 236 Diesel</b>		
1983-1975		
Belt - Fan & Alt. ....	517344M2	▲9540HD
Hose - Upper .....		☞<20355
	or	●25477
Hose - Lower .....		☞<20993

☞<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>270</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1986-1983		
Belt - Fan & Alt. ....	1809095M2	▲9590HD
Hose - Lower .....		●26502
<b>274</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1987-1982		
Belt - Fan & Alt. ....	1446980M1	▲9476HD
<b>275</b>		
<b>Perkins 4-Cyl. 248 Diesel</b>		
1983-1975		
Belt - Fan & Alt. ....	517344M2	▲9540HD
Hose - Upper .....		≠20355
		or ●25477
Hose - Lower .....		≠20993
<b>283 Special</b>		
<b>Perkins 4-Cyl. 248 Diesel</b>		
1998-1985		
Belt - Fan & Alt. ....	532779M92	②7520
<b>285</b>		
<b>Perkins 4-Cyl. 318 Diesel</b>		
1982-1974		
Belt - Fan & Alt. ....	532779M92	②7520
Hose - Upper .....		≠20611
		or ●26509
Hose - Lower .....		≠21256
		or ●26501
Hose - By Pass .....		≠20357
<b>290</b>		
<b>Perkins 4-Cyl. 248 Diesel</b>		
1986-1983		
Belt - Fan & Alt. ....	517344M2	▲9540HD
<b>294</b>		
<b>Perkins 4-Cyl. 248 Diesel</b>		
1989-1982		
Belt - Fan & Alt. ....	1446980M1	▲9476HD
Hose - Lower .....		●26502
<b>302 Industrial</b>		
<b>Continental 4-Cyl. 193</b>		
1966-1962		
Belt - Fan & Gen. ....	509572M1	▲9425HD
Hose - Upper .....		24224
<b>Perkins 4-Cyl. 203 Diesel</b>		
1966-1962		
Belt - Fan & Alt. ....	512747M1	▲9530HD
Belt - Fan & Gen. ....	186750M1	▲9476HD
Hose - Lower .....		●25478
<b>303 Industrial</b>		
<b>Perkins 4-Cyl. 208</b>		
1960-1958		
Belt - Fan & Gen. ....	764926M1	▲9435HD
Belt - Hyd. Pump .....		▲9470HD
Hose - Upper; Ser. No. 1270 & Before .....		≠20957
		or ●26603
Hose - Upper; Ser. No. 1271 & After .....		≠20957
		or ●26501
Hose - Lower; Ser. No. 1270 & Before .....		≠20357
Hose - Lower; Ser. No. 1271 & After .....		24228
<b>304</b>		
<b>Continental 4-Cyl. 193</b>		
1966-1962		
Belt - Fan & Gen. ....	509572M1	▲9425HD

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>304 - Continued</b>		
<b>Continental 4-Cyl. 193 - Continued</b>		
1966-1962 - Continued		
Hose - Upper .....		24224
<b>Perkins 4-Cyl. 203 Diesel</b>		
1966-1962		
Belt - Fan & Alt. ....	512747M1	▲9530HD
Belt - Fan & Gen. ....	186750M1	▲9476HD
Hose - Lower .....		●25478
<b>354</b>		
<b>Perkins 3-Cyl. 152 Diesel</b>		
1999-1994		
Hose - Upper .....		24428
Hose - By Pass - Eng. To W.P. ....		21528
Hose - By Pass - W.P. To Tee .....		24220
<b>356</b>		
<b>Continental 4-Cyl. 193</b>		
1966-1961		
Belt - Fan & Gen. ....	509572M1	▲9425HD
Hose - Upper .....		24224
Hose - Lower .....		●25478
<b>Perkins 4-Cyl. 203 Diesel</b>		
1966-1961		
Belt - Fan & Gen. ....	186750M2	▲9476HD
<b>362</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1998-1990		
Belt - Fan & Alt. ....	3612115M1	▲9451HD
<b>374</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1999-1989		
Belt - Fan & Alt.; W/46 1/2" Belt O.C. ....	3637595M1	②▲9463HD
Belt - Fan & Alt.; W/47 1/2" Belt O.C. ....	3637597M1	②▲9476HD
<b>375</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1998-1987		
Belt - A.C. ....	1690692M1	▲9415HD
Belt - Fan & Alt. ....	1693745M1	▲9585HD
<b>383</b>		
<b>Perkins 4-Cyl. 248 Diesel</b>		
1998-1986		
Belt - A.C. ....	1690692M1	▲9415HD
Belt - Fan & Alt. ....	1693745M1	▲9585HD
<b>384</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1998-1989		
Belt - Fan & Alt.; W/46 1/2" Belt O.C. ....	3637595M1	②▲9463HD
Belt - Fan & Alt.; W/47 1/2" Belt O.C. ....	3637597M1	②▲9476HD
<b>390</b>		
<b>Perkins 4-Cyl. 248 Diesel</b>		
1998-1987		
Belt - A.C. ....		▲9415HD
Belt - Fan & Alt. ....		▲9585HD
<b>390T</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1998-1989		
Belt - A.C. ....		▲9365HD
Belt - Fan & Alt. ....	1686615M91	②7590

②Two Required ≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>393</b>		
Perkins 4-Cyl. 236 Diesel		
1998-1992		
Belt - Fan & Alt. ....	3381364M91	②7525
<b>394</b>		
Perkins 4-Cyl. 248 Diesel		
1999-1989		
Hose - Upper .....		24272
<b>396</b>		
Perkins 6-Cyl. 365 Diesel		
1998-1992		
Belt - Fan & Alt. ....	3381364M91	②7525
Hose - Upper .....		●26510
Hose - By Pass .....		24228
<b>398</b>		
Perkins 4-Cyl. 236 Diesel		
1997-1987		
Belt - A.C. ....		▲9365HD
Belt - Fan & Alt.; W/1/2" Belt T.W. ....		②▲9590HD
Belt - Fan & Alt.; W/25/64" Belt T.W. ....	1686615M91	②7590
<b>399</b>		
Perkins 6-Cyl. 354 Diesel		
1990-1987		
Belt - Fan & Alt. ....		②▲9565HD
Hose - Upper .....		●26510
Hose - By Pass .....		24232
Perkins 6-Cyl. 365 Diesel		
1998-1991		
Belt - Fan & Alt. ....		②▲9565HD
Hose - Upper .....		●26510
Hose - By Pass .....		24232
<b>563</b>		
Perkins 3-Cyl. 202 Diesel		
2008-2006		
Belt - Fan .....	3637306M91	②▲9505HD
<b>670</b>		
Perkins 4-Cyl. 236 Diesel		
1986-1983		
Belt - Fan & Alt. ....	1686614M91	②7541
Belt - Fan To A.C. ....		▲9405HD
<b>690</b>		
Perkins 4-Cyl. 248 Diesel		
1986-1983		
Belt - Fan & Alt. ....	1686614M91	②7541
Belt - Fan To A.C. ....		▲9405HD
Hose - Upper .....		②21794
		or ●25478
Hose - Lower .....		●25480
<b>698</b>		
Perkins 4-Cyl. 318 Diesel		
1986-1983		
Belt - A.C. ....		②▲9420HD
Belt - Fan & Alt. ....	1686615M91	②7590
Hose - Upper .....		②21379
		or ●26515
<b>1001</b>		
Continental 4-Cyl. 208		
1961-1958		
Belt - Fan & Gen. ....	764926M1	▲9435HD
Hose - Upper .....		②20957
		or ●26603
Hose - Lower; Ser. No. 100381 & Before .....		24428

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>1001 - Continued</b>		
Continental 4-Cyl. 208 - Continued		
1961-1958 - Continued		
Hose - Lower; Ser. No. 100382 & After .....		②20357
		or ●26601
<b>1010</b>		
Toyosha 3-Cyl. 53 Diesel		
1994-1982		
Belt - Fan & Alt. ....	3284081M1	▲9360HD
Hose - Upper .....		●25249
Hose - Lower .....		●25252
<b>1020</b>		
Toyosha 3-Cyl. 69 Diesel		
1994-1983		
Belt - Fan & Alt. ....		▲9380HD
<b>1030</b>		
Toyosha 3-Cyl. 87 Diesel		
1994-1984		
Belt - Fan & Alt.; W/41 3/4" Belt O.C. ....		▲9415HD
Belt - Fan & Alt.; W/42 1/4" Belt O.C. ....		▲9420HD
<b>1035</b>		
Toyosha 3-Cyl. 92 Diesel		
1991-1986		
Belt - Fan & Alt. ....		▲9451HD
<b>1045</b>		
Toyosha 3-Cyl. 122 Diesel		
1991-1986		
Belt - Fan & Alt. ....		▲9430HD
<b>1080</b>		
Perkins 4-Cyl. 318 Diesel		
1972-1967		
Belt - A.C. ....	522063M1	▲9440HD
Belt - Fan & Alt.; W/A.C. ....	522061M91	②7603
Belt - Fan & Alt.; W/O A.C. ....	516467M1	▲9605HD
Hose - Upper; W/O A.C. ....		②20611
		or ●26509
Hose - Lower; W/O A.C. ....		●26505
Hose - By Pass .....		②20801
<b>1085</b>		
Perkins 4-Cyl. 318 Diesel		
1979-1972		
Belt - Fan & Alt. ....	529900M91	②7597
Hose - Upper; W/O A.C. ....		②20611
		or ●26509
Hose - Lower; W/O A.C. ....		●26505
Hose - By Pass .....		②20801
<b>1100</b>		
Perkins 6-Cyl. 354 Diesel		
1972-1964		
Belt - A.C. ....	521110M1	▲9420HD
Belt - Fan & Alt.; W/A.C.; W/58 1/8" Belt O.C. ....	517951M91	②7575
Belt - Fan & Alt.; W/A.C.; W/59 1/8" Belt O.C. ....	521398M91	②7585
Belt - Fan & Alt.; W/O A.C.; W/57 1/4" Belt O.C. ....		▲9570HD
Belt - Fan & Alt.; W/O A.C.; W/58 1/4" Belt O.C. ....	513133M1	▲9580HD
Belt - Fan & Alt.; W/O A.C.; W/58 1/8" Belt O.C. ....	517951M91	②7575
Hose - Upper .....		②20611
		or ●26510
Hose - Lower; Ser. No. 9B17222 & Before .....		●26509
Hose - Lower; Ser. No. 9B17223 & After .....		●26508
Hose - By Pass .....		②20685

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>1100 - Continued</b>		
<b>Waukesha 6-Cyl. 320</b>		
1972-1964		
Belt - Fan & Alt. ....	513116M1	▲9550HD
<b>1105</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1979-1972		
Belt - A.C. ....	529964M1	▲9430HD
Belt - Fan & Alt. ....	517951M91	②7575
Hose - Upper .....		≠21379
		or ●26510
Hose - Lower .....		●26509
Hose - By Pass; Molded Hose .....		≠20685
Hose - By Pass; Strt. Hose .....		24432
<b>1130</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1972-1964		
Belt - A.C. ....	521110M1	▲9420HD
Belt - Fan & Alt.; Ser. No. 9B13589 & Before; W/Single Belt .....	503727M1	▲9570HD
Belt - Fan & Alt.; Ser. No. 9B13590 & After; W/Single Belt .....	513133M1	▲9580HD
Belt - Fan & Alt.; W/Dual Belts .....	517951M91	②7575
Hose - Upper .....		≠20611
		or ●26510
Hose - Lower; Ser. No. 9B16950 & Before .....		●26509
Hose - Lower; Ser. No. 9B16951 & After .....		●26508
Hose - By Pass; Molded Hose .....		≠20685
Hose - By Pass; Strt. Hose .....		24432
<b>1135</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1978-1972		
Belt - Fan & Alt. ....	517951M91	②7575
Hose - Upper .....		≠21379
		or ●26510
Hose - Lower .....		●26509
Hose - By Pass; Molded Hose .....		≠20685
Hose - By Pass; Strt. Hose .....		24432
<b>1140; 1145</b>		
<b>Iseki 3-Cyl. 91 Diesel</b>		
1992-1991		
Belt - Fan & Alt. ....	62136710070	▲9390HD
<b>1150</b>		
<b>Perkins V-8 511 Diesel</b>		
1972-1967		
Belt - A.C. ....	521370M1	▲9470HD
Belt - Fan & Alt.; W/A.C. ....	518505M1	▲9330HD
Belt - Fan & Alt.; W/O A.C. ....	518506M92	②7525
Belt - Idler .....	521411M2	②7530
Hose - Upper .....		②24432
Hose - Lower .....		●26508
Hose - By Pass .....		≠20046
<b>1155</b>		
<b>Perkins V-8 540 Diesel</b>		
1978-1972		
Belt - Alt.; W/O A.C. ....	518505M1	▲9330HD
Belt - Alt. & A.C. ....	521370M1	▲9465HD
Belt - Fan .....	518506M92	②7525
Hose - Upper .....		②24432
Hose - Lower; W/14" Hose .....		●26521
Hose - Lower; W/17" Hose .....		≠20401
		or ●26522
Hose - By Pass; Molded Hose .....		≠20685
Hose - By Pass; Strt. Hose .....		24228
<b>1500</b>		
<b>Caterpillar V-8 573 Diesel</b>		
1974-1971		
Belt - A.C.; W/35 1/4" Belt O.C. ....	530329M1	▲9350HD

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>1500 - Continued</b>		
<b>Caterpillar V-8 573 Diesel - Continued</b>		
1974-1971 - Continued		
Belt - A.C.; W/38 1/4" Belt O.C. ....	533902M1	▲9380HD
Belt - Alt. ....		②▲9650HD
Belt - Fan .....	525833M1	▲9485HD
Belt - W.P. ....	530328M1	▲9400HD
Hose - Upper .....		●26512
Hose - Lower .....		≠20206
		or ●26515
<b>1505</b>		
<b>Caterpillar V-8 636 Diesel</b>		
1977-1974		
Belt - A.C.; W/35 1/4" Belt O.C. ....	530329M1	▲9350HD
Belt - A.C.; W/38 1/4" Belt O.C. ....	533902M1	▲9380HD
Belt - Alt. ....		②▲9650HD
Belt - Fan .....	525833M1	▲9485HD
Belt - W.P. ....	530328M1	▲9400HD
Hose - Upper .....		●26512
Hose - Lower .....		≠20431
<b>1528</b>		
<b>Iseki 3-Cyl. 89 Diesel</b>		
2006-2005		
Belt - Alt. ....		▲9400HD
<b>1529; 1532</b>		
<b>Iseki 3-Cyl. 91 Diesel</b>		
2014-2007		
Belt - Fan .....	3607417M1	▲9385HD
<b>1533</b>		
<b>Iseki 3-Cyl. 91 Diesel</b>		
2014-2005		
Belt - Fan .....	3607417M1	▲9385HD
<b>1540</b>		
<b>Iseki 3-Cyl. 91 Diesel</b>		
2006-2005		
Belt - Alt. ....		▲9405HD
<b>1560</b>		
<b>Iseki 4-Cyl. 180 Diesel</b>		
2008-2006		
Belt - Fan .....		▲9447HD
<b>1635</b>		
<b>Iseki 3-Cyl. 101 Diesel</b>		
2013-2009		
Belt - Fan .....	4264647M1	▲9435HD
<b>1800</b>		
<b>Caterpillar V-8 636 Diesel</b>		
1974-1971		
Belt - A.C.; W/35 1/4" Belt O.C. ....	530329M1	▲9350HD
Belt - A.C.; W/38 1/4" Belt O.C. ....	533902M1	▲9380HD
Belt - Alt. ....		②▲9650HD
Belt - Fan .....	525833M1	▲9485HD
Belt - W.P. ....	530328M1	▲9400HD
Hose - Upper .....		●26512
Hose - Lower .....		≠20206
		or ●26515
<b>1805</b>		
<b>Caterpillar V-8 636 Diesel</b>		
1978-1974		
Belt - A.C.; W/35 1/4" Belt O.C. ....	530329M1	▲9350HD
Belt - A.C.; W/38 1/4" Belt O.C. ....	533902M1	▲9380HD
Belt - Alt. ....		②▲9650HD
Belt - Fan .....	525833M1	▲9485HD
Belt - W.P. ....	530328M1	▲9400HD
Hose - Upper .....		●26512

②Two Required ≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>1805 - Continued</b>		
<b>Caterpillar V-8 636 Diesel - Continued</b>		
1978-1974 - Continued		
Hose - Lower .....		≈20431
<b>2135 Turf; 2135 Utility</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1968-1964		
Belt - Fan & Gen. ....	186976M1	♣9490HD
Hose - Upper .....		24224
Hose - Lower .....		●25477
Hose - By Pass .....		24224
<b>Perkins 4-Cyl. 134</b>		
1968-1964		
Belt - Fan & Alt. ....	509572M1	♣9425HD
Belt - Fan & Gen. ....	181523M1	♣9430HD
Hose - Upper .....		●25472
Hose - Lower .....		≈20416
		or ●25473
Hose - By Pass .....		24224
<b>2200 Industrial</b>		
<b>Perkins 3-Cyl. 152 Diesel</b>		
1970-1965		
Belt - Fan & Gen. ....	186976M1	♣9490HD
Hose - Upper .....		●25476
Hose - By Pass .....		24220
<b>Perkins 4-Cyl. 134</b>		
1970-1965		
Belt - Fan & Alt. ....	509572M1	♣9425HD
Belt - Fan & Gen. ....	181523M1	♣9430HD
Hose - Upper .....		●25476
<b>2640</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1983-1982		
Belt - A.C. ....		♣9465HD
Belt - Alt. ....		♣9395HD
Belt - Fan .....	3045111M91	②♣9585HD
Belt - Fan & Alt. ....		②♣9600HD
Hose - Upper .....		●26501
<b>2675</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1983-1978		
Belt - A.C.; W/44 7/8" Belt O.C. ....		♣9447HD
Belt - A.C.; W/45 7/8" Belt O.C. ....	1614371M1	♣9455HD
Belt - Fan .....	3045111M1	②♣9585HD
Belt - W.P. & Alt.; Ser. No. 9R8413 & Before .....	3320327M1	♣9400HD
Belt - W.P. & Alt.; Ser. No. 9R8414 & After ..	3040366M1	♣9395HD
Hose - Upper .....		②24232
Hose - Lower .....		●26522
<b>2705</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1983-1978		
Belt - A.C.; Ser. No. 9R5659 & Before .....		♣9447HD
Belt - A.C.; Ser. No. 9R5660 & After .....	3324169M1	♣9480HD
Belt - Fan & Alt. ....	3040950M91	A56
Hose - Upper .....		②24232
Hose - Lower .....		●26522
<b>2745</b>		
<b>Perkins V-8 539 Diesel</b>		
1983-1978		
Belt - A.C. ....	3038999M1	♣9540HD
Belt - Fan .....	1613267M1	②♣9620HD
Belt - Fan & Alt. ....	1613293M1	②7560

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>2770</b>		
<b>Perkins V-8 640 Diesel</b>		
1983-1977		
Belt - A.C. ....	3038999M1	♣9540HD
Belt - Fan .....	1613267M1	②♣9620HD
Belt - Fan & Alt. ....	1613293M1	②7560
<b>2775</b>		
<b>Perkins V-8 640 Diesel</b>		
1983-1978		
Belt - A.C. ....	3038999M1	♣9540HD
Belt - Fan .....	1613267M1	②♣9620HD
Belt - Fan & Alt. ....	1613293M1	②7560
Hose - Upper .....		②●26520
<b>2800</b>		
<b>Perkins V-8 640 Diesel</b>		
1977-1976		
Belt - A.C. ....	3038999M1	♣9540HD
Belt - Fan .....	1613267M1	②♣9620HD
Belt - Fan & Alt. ....	1613293M1	②7560
<b>2805</b>		
<b>Perkins V-8 640 Diesel</b>		
1983-1978		
Belt - A.C. ....	3038999M1	♣9540HD
Belt - Fan .....	1613267M1	②♣9620HD
Belt - Fan & Alt. ....	1613293M1	②7560
Hose - Upper - Eng. To Pipe .....		②≈20748
Hose - Upper - Pipe To Rad. ....		②≈21194
		or ②●26519
<b>3060</b>		
<b>Perkins 4-Cyl. 248 Diesel</b>		
1993-1987		
Hose - Upper .....		≈21379
Hose - Lower .....		●26509
Hose - By Pass .....		24232
<b>3090</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1991-1987		
Belt - Fan & A.C. ....		♣9440HD
Belt - Fan & Alt.; W/59 1/4" Belt O.C. ....		②♣9590HD
Belt - Fan & Alt.; W/60 1/4" Belt O.C. ....		②♣9600HD
Hose - Upper .....		≈21379
Hose - Lower .....		●26509
Hose - By Pass .....		24232
<b>3120</b>		
<b>Perkins 6-Cyl. 365 Diesel</b>		
1993-1990		
Belt - Fan To A.C. ....		♣9485HD
Hose - Upper .....		≈21379
Hose - By Pass .....		24224
<b>3165 Industrial</b>		
<b>Continental 4-Cyl. 176</b>		
1967-1964		
Belt - Fan & Gen. ....	189789M1	♣9485HD
Hose - Upper .....		≈20065
Hose - Lower .....		●25474
Hose - By Pass; Molded Hose .....		≈20267
Hose - By Pass; Strt. Hose .....		24216
<b>Perkins 4-Cyl. 203 Diesel</b>		
1967-1964		
Belt - Fan & Gen. ....	189789M1	♣9485HD
Hose - Upper .....		≈20065
Hose - Lower .....		●25474
Hose - By Pass; Molded Hose .....		≈20267
Hose - By Pass; Strt. Hose .....		24216

②Two Required ≈Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>3505</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1987-1984		
Belt - A.C.; W/42 3/4" Belt O.C. ....		▲9425HD
Belt - A.C.; W/45 3/4" Belt O.C. ....		▲9455HD
Belt - A.C.; W/47 1/4" Belt O.C. ....		▲9470HD
Belt - Fan & Alt.; W/39 7/8" Belt O.C. ....	3040966M1	▲9395HD
Belt - Fan & Alt.; W/55 3/4" Belt O.C. ....		②▲9555HD
Belt - Fan & Alt.; W/58 3/4" Belt O.C. ....	3045111M91	②▲9585HD
Hose - Upper; W/1 3/4" I.D. Rad. Spout .....		●26502
Hose - Upper; W/2" I.D. Rad. Spout .....		●26509
Hose - By Pass .....		24232
<b>3525; 3545</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1987-1984		
Belt - A.C.; W/42 3/4" Belt O.C. ....		▲9425HD
Belt - A.C.; W/45 3/4" Belt O.C. ....		▲9455HD
Belt - A.C.; W/47 1/4" Belt O.C. ....		▲9470HD
Belt - Fan & Alt.; W/55 3/4" Belt O.C. ....		②▲9555HD
Belt - Fan & Alt.; W/58 3/4" Belt O.C. ....	3045111M91	②▲9585HD
Hose - Upper; W/1 3/4" I.D. Rad. Spout .....		●26502
Hose - Upper; W/2" I.D. Rad. Spout .....		●26509
Hose - By Pass .....		24232
<b>3625; 3635; 3645</b>		
<b>Sisu 3-Cyl. 201 Diesel</b>		
2007		
Belt - Fan & Alt.; Ser. No. S13002 & Before .....	VA205892	▲9510HD
<b>3660</b>		
<b>Perkins 6-Cyl. 365 Diesel</b>		
1995-1990		
Belt - Fan & Alt. ....		▲9640HD
Belt - Fan To A.C. ....		②▲9455HD
Hose - Upper .....		③<21379
Hose - By Pass .....		24224
<b>4243</b>		
<b>Perkins 4-Cyl. 244 Diesel</b>		
2001-1997		
Belt - A.C. ....	1686883M1	▲9435HD
Belt - Alt. ....		②▲9520HD
<b>4800</b>		
<b>Cummins V-8 903 Diesel</b>		
1986-1980		
Belt - A.C.; Ser. No. 9D004000 & Before .....	595851M1	▲9560HD
Belt - A.C.; Ser. No. 9D004001 & After .....	512431M1	▲9580HD
Belt - Fan & Alt.; Ser. No. 9D003701 & Before .....	517456M1	▲9500HD
Belt - Fan & Alt.; Ser. No. 9D004281 & After .....	517344M1	▲9540HD
Belt - Fan & Alt.; Ser. No. 9D3702 Thru 9D004280 .....	513833M1	▲9520HD
Hose - Upper .....		●26527
Hose - Lower .....		●26536
<b>4840; 4880</b>		
<b>Cummins V-8 903 Diesel</b>		
1986-1978		
Belt - A.C.; Ser. No. 9D004000 & Before .....	595851M1	▲9560HD
Belt - A.C.; Ser. No. 9D004001 & After .....	512431M1	▲9580HD
Belt - Fan & Alt.; Ser. No. 9D003701 & Before .....	517456M1	▲9500HD
Belt - Fan & Alt.; Ser. No. 9D004281 & After .....	517344M1	▲9540HD
Belt - Fan & Alt.; Ser. No. 9D3702 Thru 9D004280 .....	513833M1	▲9520HD
Hose - Upper .....		②<20731
		or ②●26524

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>4900</b>		
<b>Cummins V-8 903 Diesel</b>		
1986-1980		
Belt - A.C.; Ser. No. 9D004000 & Before .....	595851M1	▲9560HD
Belt - A.C.; Ser. No. 9D004001 & After .....	512431M1	▲9580HD
Belt - Fan & Alt.; Ser. No. 9D003701 & Before .....	517456M1	▲9500HD
Belt - Fan & Alt.; Ser. No. 9D004281 & After .....	517344M1	▲9540HD
Belt - Fan & Alt.; Ser. No. 9D3702 Thru 9D004280 .....	513833M1	▲9520HD
Hose - Upper .....		②<21378
<b>5200</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1993-1989		
Belt - Alt. ....		②▲9565HD
Belt - Fan .....		③▲9510HD
Belt - Fan To A.C. ....		▲9670HD
Hose - Lower .....		●26531
<b>Detroit Diesel 6-Cyl. 774 Diesel</b>		
1993-1989		
Belt - Alt. ....		②▲9565HD
Belt - Fan .....		③▲9510HD
Belt - Fan To A.C. ....		▲9670HD
Hose - Lower .....		●26531
<b>5435</b>		
<b>Perkins 4-Cyl. 268 Diesel</b>		
2007		
Belt - Fan & Alt.; For High Visibility Tractor ..	3780604M91	②▲9510HD
2006		
Belt - Fan & Alt.; Exc. High Visibility Tractor; Ser. No. R033030 & Before .....	4274693M91	②▲9570HD
Belt - Fan & Alt.; For High Visibility Tractor; Ser. No. R012051 & Before .....	3777681M91	②▲9520HD
Belt - Fan & Alt.; For High Visibility Tractor; Ser. No. R012052 & After .....	3780604M91	②▲9510HD
2005-2004		
Belt - Fan & Alt.; Exc. High Visibility Tractor .....	4274693M91	②▲9570HD
Belt - Fan & Alt.; For High Visibility Tractor ..	3777681M91	②▲9520HD
<b>Perkins 4-Cyl. 269 Diesel</b>		
2009-2008		
Belt - Fan & Alt.; For High Visibility Tractor ..	3780604M91	②▲9510HD
<b>5465</b>		
<b>Perkins 6-Cyl. 365 Diesel</b>		
2007		
Belt - Serpentine - A.C.; W/Air Brake Compr. ....	4281725M1	K060642 or K060642RPM
Belt - A.C.; W/V-Belt Drive .....	4272496M1	▲9500HD
Belt - Fan; W/V-Belt Drive .....	3780606M91	②▲9560HD
2006		
Belt - A.C. ....	4272496M1	▲9500HD
Belt - Fan .....	3780606M91	②▲9560HD
<b>Perkins 6-Cyl. 402 Diesel</b>		
2009-2008		
Belt - Serpentine - A.C.; W/Air Brake Compr. ....	4281725M1	K060642 or K060642RPM
<b>6485</b>		
<b>Sisu 6-Cyl. 402 Diesel</b>		
2006-2004		
Belt - Serpentine - Accessory Drive; W/120A. Alt. ....	4273187M1	▲K080680HD
Belt - Serpentine - Accessory Drive; W/150A. Alt. ....	4273188M1	▲K080685HD

②Two Required ③Three Required <Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

**TRACTORS**



Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>6490</b>		
<b>Sisu 6-Cyl. 402 Diesel</b>		
2006-2004		
Belt - Serpentine - Accessory Drive; W/120A. Alt. ....	4273187M1	♣K080680HD
<b>6499</b>		
<b>Sisu 6-Cyl. 451 Diesel</b>		
2009-2008		
Belt - Serpentine - Fan & Alt. ....	4284981M1	♣K080718HD
<b>7495</b>		
<b>Sisu 6-Cyl. 402 Diesel</b>		
2007-2004		
Belt - Serpentine - Fan & Alt.; W/120A. Alt. .	4273187M1	♣K080680HD
Belt - Serpentine - Fan & Alt.; W/150A. Alt. .	4273188M1	♣K080685HD
<b>8270</b>		
<b>Valmet 6-Cyl. 513 Diesel</b>		
2004-1999		
Belt - Serpentine - Accessory Drive .....	V836859142	♣K120774HD
<b>8450 Tractor</b>		
<b>Sisu 6-Cyl. 451 Diesel</b>		
2009-2007		
Belt - Serpentine - A.C. ....	4281345M1	♣K080433HD
Belt - Serpentine - Fan & Alt. ....	4284981M1	♣K080718HD
2006-2005		
Belt - Serpentine - A.C. ....	4281345M1	♣K080433HD
Belt - Serpentine - Fan & Alt. ....	4275919M1	♣K080765HD
<b>8460 Tractor</b>		
<b>Sisu 6-Cyl. 451 Diesel</b>		
2007		
Belt - Serpentine - A.C. ....	4281345M1	♣K080433HD
Belt - Serpentine - Fan & Alt. ....	4284981M1	♣K080718HD
2006-2005		
Belt - Serpentine - A.C. ....	4281345M1	♣K080433HD
Belt - Serpentine - Fan & Alt. ....	4275919M1	♣K080765HD
<b>8680</b>		
<b>Cummins 6-Cyl. 8.3 L Diesel</b>		
2005-1999		
Belt - A.C. ....	71148120	♣9510HD
Belt - Clean Grain Elevator .....	71368809	C180
Belt - Tailings Drive .....	71367460	C100
1998-1997		
Belt - A.C. ....	71369747	♣9480HD
Belt - Clean Grain Elevator .....	71368809	C180
Belt - Tailings Drive .....	71367460	C100
<b>MF200</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1976-1966		
Belt - Fan .....	508560M1	♣9370HD
Belt - Fan To Alt. ....	508588M2	♣9319HD
<b>MF200B</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1977-1976		
Belt - Fan .....	2740015M1	9295
<b>MF300</b>		
<b>Perkins 4-Cyl. 248 Diesel</b>		
1977-1969		
Belt - Fan & Alt.; Ser. No. 248UA14402L & Before .....		♣9470HD
Belt - Fan & Alt.; Ser. No. 248UA17092		②7475
Thru 248UA88561 .....	1446046M1	②7470
Belt - Fan & Alt.; Ser. No. 248UA88561 & After .....		●26504
Hose - Upper .....		②20957
Hose - Lower .....		or ●26603

Application	OEM No.	Our No.
<b>MASSEY FERGUSON - Continued</b>		
<b>MF2244</b>		
<b>Perkins 3-Cyl. 153 Diesel</b>		
1971-1967		
Belt - Fan .....	508560M1	♣9370HD
Belt - Fan To Alt. ....	508588M2	♣9319HD
<b>MASSEY HARRIS</b>		
<b>20</b>		
<b>Continental 4-Cyl. 124</b>		
1948-1946		
Belt - Fan & Gen. ....	33365A	TR28423
<b>22</b>		
<b>Continental 4-Cyl. 140</b>		
1955-1948		
Belt - Fan & Gen. ....	33365A	TR28423
<b>33</b>		
<b>Massey Harris 4-Cyl. 201</b>		
1955-1952		
Belt - Fan & Gen. ....	764926M1	♣9435HD
<b>33D</b>		
<b>Massey Harris 4-Cyl. 201 Diesel</b>		
1955-1952		
Belt - Fan & Gen. ....	764926M1	♣9435HD
<b>44</b>		
<b>Massey Harris 4-Cyl. 259</b>		
1955-1946		
Belt - Fan & Gen.; W/49 1/4" Belt O.C. ....	767356M1	♣9490HD
Belt - Fan & Gen.; W/50 1/8" Belt O.C. ....	35645A	TR34495
<b>44-6</b>		
<b>Continental 6-Cyl. 226</b>		
1951-1946		
Belt - Fan & Gen. ....	34488A	TR34467
<b>44D</b>		
<b>Massey Harris 4-Cyl. 259 Diesel</b>		
1955-1946		
Belt - Fan & Gen.; W/49 1/4" Belt O.C. ....	767356M1	♣9490HD
Belt - Fan & Gen.; W/50 1/8" Belt O.C. ....	35645A	TR34495
<b>333</b>		
<b>Massey Harris 4-Cyl. 208</b>		
1958-1956		
Belt - Fan & Gen. ....	764926M1	♣9435HD
Hose - Upper .....		②20957
		or ●26603
Hose - Lower .....		②20357
		or ●26601
<b>Massey Harris 4-Cyl. 208 Diesel</b>		
1958-1956		
Belt - Fan & Gen. ....	764926M1	♣9435HD
Hose - Upper .....		②20957
		or ●26603
Hose - Lower .....		②20357
		or ●26601
<b>444</b>		
<b>Massey Harris 4-Cyl. 277</b>		
1958-1956		
Belt - Fan & Gen. ....	767356M1	♣9490HD
Hose - Upper .....		②20957
Hose - Lower .....		24224
<b>Massey Harris 4-Cyl. 277 Diesel</b>		
1958-1956		
Belt - Fan & Gen. ....	767356M1	♣9490HD
Hose - Upper .....		②20957

②Two Required ③Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MASSEY HARRIS - Continued</b>		
<b>444 - Continued</b>		
<b>Massey Harris 4-Cyl. 277 Diesel - Continued</b>		
1958-1956 - Continued		
Hose - Lower .....		24224
<b>Massey Harris 4-Cyl. 277 LPG</b>		
1958-1956		
Belt - Fan & Gen. ....	767356M1	▲9490HD
Hose - Upper .....		✕20957
Hose - Lower .....		24224
<b>Colt 21</b>		
<b>Continental 4-Cyl. 124</b>		
1954-1952		
Belt - Fan & Gen. ....	33365A	TR28423
<b>Mustang 23</b>		
<b>Continental 4-Cyl. 140</b>		
1956-1952		
Belt - Fan & Gen. ....	33365A	TR28423
<b>Pacer 16</b>		
<b>Continental 4-Cyl. 91</b>		
1957-1954		
Belt - Fan & Gen. ....	852175M1	TR22386
<b>Pony 11</b>		
<b>Continental 4-Cyl. 62</b>		
1957-1947		
Belt - Fan & Gen. ....	850320M1	TR22373
<b>MINNEAPOLIS-MOLINE</b>		
<b>4-Star</b>		
<b>Minneapolis-Moline 4-Cyl. 206</b>		
1962-1959		
Belt - Fan & Gen. ....	10A7486	7508
<b>5-Star</b>		
<b>Minneapolis-Moline 4-Cyl. 283</b>		
1961-1957		
Belt - Fan .....	10A9870	TR24476
Belt - Gen. ....	10A9733	7330
Hose - Upper .....		24226
<b>Minneapolis-Moline 4-Cyl. 336 Diesel</b>		
1961-1957		
Belt - Fan .....	10A9870	TR24476
Belt - Gen. ....	10A9733	7330
Hose - Upper .....		24226
<b>335 Industrial</b>		
<b>Minneapolis-Moline 4-Cyl. 165</b>		
1960-1957		
Belt - Fan & Gen. ....	10A7486	7508
<b>335 Universal</b>		
<b>Minneapolis-Moline 4-Cyl. 165</b>		
1959-1957		
Belt - Fan & Gen. ....	10A7486	7508
<b>335 Utility</b>		
<b>Minneapolis-Moline 4-Cyl. 165</b>		
1961-1956		
Belt - Fan & Gen. ....	10A7486	7508
<b>445 Industrial; 445 Universal</b>		
<b>Minneapolis-Moline 4-Cyl. 206</b>		
1959-1956		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		✕20791

Application	OEM No.	Our No.
<b>MINNEAPOLIS-MOLINE - Continued</b>		
<b>445 Industrial; 445 Universal - Continued</b>		
<b>Minneapolis-Moline 4-Cyl. 206 Diesel</b>		
1959-1956		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		✕20791
<b>445U Utility</b>		
<b>Minneapolis-Moline 4-Cyl. 206</b>		
1959-1956		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		✕20791
<b>Minneapolis-Moline 4-Cyl. 206 Diesel</b>		
1960-1959		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		✕20791
1957-1956		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		✕20791
<b>A4T1400</b>		
<b>Minneapolis-Moline 6-Cyl. 504</b>		
1970-1969		
Belt - Fan & Alt. ....	10A30623	②▲9580HD
Belt - P.S. ....	10A31206	②7450
Hose - Upper; W/1 3/4" I.D. Hose .....		●26505
Hose - Upper - Intake Manifold To W.P. ....		24232
Hose - Lower .....		24238
<b>Minneapolis-Moline 6-Cyl. 504 Diesel</b>		
1970-1969		
Belt - Fan & Alt. ....	10A29801	▲9570HD
Belt - P.S. ....	10A30895	③7430
Hose - Upper .....		●26505
Hose - Upper - Intake Manifold To W.P. ....		24232
Hose - Lower .....		24238
<b>A4T1600</b>		
<b>Minneapolis-Moline 6-Cyl. 585 Diesel</b>		
1972-1970		
Belt - A.C. ....		▲9510HD
Belt - Fan & Alt. ....	10A30623	②▲9580HD
Belt - Hyd. Pump .....		③7480
Belt - P.S. ....	10A31206	②7450
Hose - Upper - Intake Manifold To W.P. ....		24232
Hose - Lower .....		24238
<b>BF</b>		
<b>Hercules 4-Cyl. 133</b>		
1957-1950		
Belt - Fan & Gen. ....	135087	TR24414
<b>BFH</b>		
<b>Hercules 4-Cyl. 133</b>		
1953		
Belt - Fan & Gen. ....	135087	TR24414
<b>BG</b>		
<b>Hercules 4-Cyl. 133</b>		
1957-1950		
Belt - Fan & Gen. ....	135087	TR24414
<b>Big Mo 400</b>		
<b>Minneapolis-Moline 4-Cyl. 206</b>		
1964-1961		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		✕20791
Hose - Lower .....		●25478
<b>Minneapolis-Moline 4-Cyl. 206 Diesel</b>		
1963-1959		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		✕20791
Hose - Lower .....		●25478

②Two Required ③Three Required ✕Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>MINNEAPOLIS-MOLINE - Continued</b>		
<b>Big Mo 500</b>		
<b>Minneapolis-Moline 4-Cyl. 206</b>		
1966-1960		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		☞20791
Hose - Lower .....		●25478
<b>Minneapolis-Moline 4-Cyl. 206 Diesel</b>		
1965-1960		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		☞20791
Hose - Lower .....		●25478
<b>Big Mo 600</b>		
<b>Minneapolis-Moline 4-Cyl. 206</b>		
1961-1960		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		☞20791
Hose - Lower .....		●25478
<b>G</b>		
<b>Minneapolis-Moline 4-Cyl. 403</b>		
1955-1950		
Belt - Fan .....		TR30467
Belt - Gen.; W/1/2" Belt T.W.; W/36 1/4" Belt O.C. ....	10A1934	♣9360HD
Belt - Gen.; W/3/8" Belt T.W.; W/36 1/8" Belt O.C. ....	10A3995	7360
Hose - Upper .....		24226
Hose - Lower .....		24226
<b>G VI</b>		
<b>Minneapolis-Moline 6-Cyl. 426</b>		
1962-1959		
Belt - Fan .....		TR30467
Belt - Gen.; W/1/2" Belt T.W.; W/36 1/4" Belt O.C. ....	10A1934	♣9360HD
Belt - Gen.; W/3/8" Belt T.W.; W/36 1/8" Belt O.C. ....	10A3995	7360
Hose - Upper .....		24928
Hose - Lower .....		☞21256
Hose - By Pass .....		28442
<b>Minneapolis-Moline 6-Cyl. 426 Diesel</b>		
1962-1959		
Belt - Fan .....		TR30467
Belt - Gen.; W/1/2" Belt T.W.; W/36 1/4" Belt O.C. ....	10A1934	♣9360HD
Belt - Gen.; W/3/8" Belt T.W.; W/36 1/8" Belt O.C. ....	10A3995	7360
Hose - Upper .....		24928
Hose - Lower .....		☞21256
Hose - By Pass .....		28442
<b>G705; G706</b>		
<b>Minneapolis-Moline 6-Cyl. 504</b>		
1965-1962		
Hose - Upper .....		24226
Hose - Lower .....		☞21256
Hose - By Pass .....		28442
<b>Minneapolis-Moline 6-Cyl. 504 Diesel</b>		
1965-1962		
Belt - Gen. ....	10A19321	7340
Hose - Upper .....		24226
Hose - Lower .....		☞21256
Hose - By Pass .....		28442

Application	OEM No.	Our No.
<b>MINNEAPOLIS-MOLINE - Continued</b>		
<b>G707</b>		
<b>Minneapolis-Moline 6-Cyl. 504 Diesel</b>		
1965		
Belt - Gen. ....	10A19321	7340
<b>G708</b>		
<b>Minneapolis-Moline 6-Cyl. 504</b>		
1965		
Belt - Gen. ....	10A19321	7340
<b>Minneapolis-Moline 6-Cyl. 504 Diesel</b>		
1965		
Belt - Gen. ....	10A19321	7340
<b>G709</b>		
<b>Minneapolis-Moline 6-Cyl. 504</b>		
1965		
Belt - Gen. ....	10A19321	7340
Hose - Upper .....		24226
Hose - Lower .....		☞21256
Hose - By Pass .....		28442
<b>Minneapolis-Moline 6-Cyl. 504 Diesel</b>		
1965		
Belt - Gen. ....	10A19321	7340
Hose - Upper .....		24226
Hose - Lower .....		☞21256
Hose - By Pass .....		28442
<b>G900</b>		
<b>Minneapolis-Moline 6-Cyl. 425</b>		
1969-1967		
Belt - Alt. & P.S.; Ser. No. 33000550 & Before .....	10A22226	♣9463HD
Belt - Fan & Alt.; Ser. No. 33000550 & Before .....	10A29137	TR28483
Belt - Fan & Alt.; Ser. No. 33000551 & After .....	10A30140	♣9510HD
Belt - Fan & P.S.; Ser. No. 33000552 & After .....	10A29338	②♣9600HD
Hose - Upper .....		●25480
<b>Minneapolis-Moline 6-Cyl. 451 Diesel</b>		
1969-1967		
Belt - Alt. & P.S.; Ser. No. 33101375 & Before .....	10A22226	♣9463HD
Belt - Fan & Alt.; Ser. No. 33101375 & Before .....	10A29137	TR28483
Belt - Fan & Alt.; Ser. No. 33101376 & After .....	10A30140	♣9510HD
Belt - Fan & P.S.; Ser. No. 33101376 & After .....	②♣9600HD	
Hose - Upper .....		●25480
<b>G950</b>		
<b>Minneapolis-Moline 6-Cyl. 425</b>		
1971-1969		
Belt - Fan & Alt. ....	10A29801	②♣9570HD
Belt - Hyd. Pump .....		7508
Belt - P.S. ....	10A30590	♣9505HD
Hose - Upper .....		●26505
Hose - By Pass; W/2 3/8" I.D. Hose .....		24238
Hose - By Pass; W/2" I.D. Hose .....		24232
<b>Minneapolis-Moline 6-Cyl. 451 Diesel</b>		
1971-1969		
Belt - Fan & Alt. ....	10A29801	②♣9570HD
Belt - Hyd. Pump .....		7508
Belt - P.S. ....	10A30590	♣9505HD
Hose - Upper .....		●26505
Hose - By Pass; W/2 3/8" I.D. Hose .....		24238
Hose - By Pass; W/2" I.D. Hose .....		24232
<b>G955</b>		
<b>Minneapolis-Moline 6-Cyl. 425</b>		
1974-1973		
Belt - Fan & Alt. ....	10A29801	②♣9570HD

②Two Required ☞Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>MINNEAPOLIS-MOLINE - Continued</b>		
<b>G955 – Continued</b>		
<b>Minneapolis-Moline 6-Cyl. 425 – Continued</b>		
1974-1973 – Continued		
Belt - Hyd. Pump .....		7508
<b>Minneapolis-Moline 6-Cyl. 451 Diesel</b>		
1974-1973		
Belt - Fan & Alt. ....	10A29801	②▲9570HD
Belt - Hyd. Pump .....		7508
<b>G1000</b>		
<b>Minneapolis-Moline 6-Cyl. 504</b>		
1969-1965		
Hose - Upper .....		●25480
<b>Minneapolis-Moline 6-Cyl. 504 Diesel</b>		
1969-1965		
Belt - Alt. & P.S.; Ser. No. 34601185 & Before .....	10A22226	▲9463HD
Belt - Fan & P.S.; Ser. No. 34601186 & After .....	10A29388	②▲9600HD
Hose - Upper .....		●25480
Hose - Lower .....		●26510
<b>G1050</b>		
<b>Minneapolis-Moline 6-Cyl. 504</b>		
1972-1969		
Belt - Fan & Alt. ....	10A29801	▲9570HD
Belt - P.S. ....	10A30590	▲9505HD
Hose - Upper .....		●26505
Hose - By Pass; W/2 3/8" I.D. Hose .....		24238
Hose - By Pass; W/2" I.D. Hose .....		24232
<b>Minneapolis-Moline 6-Cyl. 504 Diesel</b>		
1972-1969		
Belt - Fan & Alt. ....	10A29801	▲9570HD
Belt - P.S. ....	10A30590	▲9505HD
Hose - Upper .....		●26505
Hose - By Pass; W/2 3/8" I.D. Hose .....		24238
Hose - By Pass; W/2" I.D. Hose .....		24232
<b>G1350</b>		
<b>Minneapolis-Moline 6-Cyl. 504</b>		
1972-1969		
Hose - Upper; Early .....		●26513
Hose - Upper; Late .....		●26505
Hose - Upper - Intake Manifold To W.P. ....		24232
Hose - Lower; Early .....		24242
Hose - Lower; Late .....		24238
<b>Minneapolis-Moline 6-Cyl. 585 Diesel</b>		
1972-1969		
Belt - Fan & Alt. ....	10A30623	②▲9580HD
Belt - P.S. ....	10A30590	▲9505HD
Hose - Upper; Early .....		●26513
Hose - Upper; Late .....		●26505
Hose - Upper - Intake Manifold To W.P. ....		24232
Hose - Lower; Early .....		24242
Hose - Lower; Late .....		24238
<b>G1355</b>		
<b>Minneapolis-Moline 6-Cyl. 585 Diesel</b>		
1975-1972		
Belt - Fan & Alt. ....	10A30623	②▲9580HD
Belt - P.S. ....	10A30590	▲9505HD
Hose - Upper .....		●26506
Hose - Lower .....		24244
<b>GB</b>		
<b>Minneapolis-Moline 4-Cyl. 403</b>		
1959-1955		
Belt - Fan .....		TR30467
Belt - Gen.; W/1/2" Belt T.W.; W/36 1/4" Belt O.C. ....	10A1934	▲9360HD
Belt - Gen.; W/3/8" Belt T.W.; W/36 1/8" Belt O.C. ....	10A3995	7360

Application	OEM No.	Our No.
<b>MINNEAPOLIS-MOLINE - Continued</b>		
<b>GB – Continued</b>		
<b>Minneapolis-Moline 4-Cyl. 403 – Continued</b>		
1959-1955 – Continued		
Hose - Upper .....		24226
Hose - Lower .....		24226
<b>Minneapolis-Moline 6-Cyl. 425 Diesel</b>		
1959-1955		
Belt - Fan .....		TR30467
Belt - Gen.; W/1/2" Belt T.W.; W/36 1/4" Belt O.C. ....	10A1934	▲9360HD
Belt - Gen.; W/3/8" Belt T.W.; W/36 1/8" Belt O.C. ....	10A3995	7360
Hose - Upper .....		24226
Hose - Lower .....		24226
<b>GTB</b>		
<b>Minneapolis-Moline 4-Cyl. 403</b>		
1954-1947		
Belt - Fan .....		TR30467
Hose - Upper .....		24226
Hose - Lower .....		24226
<b>Minneapolis-Moline 6-Cyl. 426 Diesel</b>		
1954-1947		
Hose - Upper .....		24226
<b>GTC</b>		
<b>Minneapolis-Moline 4-Cyl. 403</b>		
1953-1951		
Belt - Fan .....		TR30467
Hose - Upper .....		24226
Hose - Lower .....		24226
<b>Jet Star 3</b>		
<b>Minneapolis-Moline 4-Cyl. 206</b>		
1970-1964		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		24222
Hose - Lower .....		●25480
<b>Minneapolis-Moline 4-Cyl. 206 Diesel</b>		
1970-1964		
Belt - Fan & Gen. ....	10A7486	7508
Hose - Upper .....		24222
Hose - Lower .....		●25480
<b>M5</b>		
<b>Minneapolis-Moline 4-Cyl. 336</b>		
1963-1960		
Belt - Fan; W/47" Belt O.C. ....	10A9870	TR24465
Belt - Gen. ....	10A9733	7330
Hose - Upper .....		24226
Hose - By Pass .....		28442
<b>Minneapolis-Moline 4-Cyl. 336 Diesel</b>		
1963-1960		
Belt - Fan; W/47" Belt O.C. ....	10A9870	TR24465
Belt - Gen. ....	10A9733	7330
Hose - Upper .....		24226
Hose - By Pass .....		28442
<b>M504</b>		
<b>Minneapolis-Moline 4-Cyl. 336</b>		
1963-1962		
Belt - Fan; W/47" Belt O.C. ....	10A9870	TR24465
Belt - Gen. ....	10A9733	7330
Hose - Upper .....		24226
Hose - By Pass .....		28442
<b>Minneapolis-Moline 4-Cyl. 336 Diesel</b>		
1963-1962		
Belt - Fan; W/47" Belt O.C. ....	10A9870	TR24465
Belt - Gen. ....	10A9733	7330
Hose - Upper .....		24226
Hose - By Pass .....		28442

②Two Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MINNEAPOLIS-MOLINE - Continued</b>		
<b>M602; M604</b>		
<b>Minneapolis-Moline 4-Cyl. 336</b>		
1964-1963		
Belt - Fan; W/47" Belt O.C. ....	10A9870	TR24465
Belt - Gen. ....	10A9733	7330
Hose - Upper .....		24226
<b>Minneapolis-Moline 4-Cyl. 336 Diesel</b>		
1964-1963		
Belt - Fan; W/47" Belt O.C. ....	10A9870	TR24465
Belt - Gen. ....	10A9733	7330
Hose - Upper .....		24226
<b>M670</b>		
<b>Minneapolis-Moline 4-Cyl. 336</b>		
1965-1964		
Belt - Alt. ....	10A22226	▲9463HD
Belt - Alt. & P.S. ....	10A29339	7455
Belt - Fan .....	10A9870	TR24465
Belt - Gen. ....	10A9733	7330
Hose - Upper; Late .....		●26509
Hose - Lower; Late .....		●26612
<b>Minneapolis-Moline 4-Cyl. 336 Diesel</b>		
1965-1964		
Belt - Alt. ....	10A22226	▲9463HD
Belt - Alt. & P.S. ....	10A29339	7455
Belt - Fan .....	10A9870	TR24465
Belt - Gen. ....	10A9733	7330
Hose - Upper; Late .....		●26509
Hose - Lower; Late .....		●26612
<b>M670 Super</b>		
<b>Minneapolis-Moline 4-Cyl. 336</b>		
1970-1966		
Belt - Alt. ....	10A22226	▲9463HD
Belt - Alt. & P.S. ....	10A29339	7455
Belt - Fan .....	10A9870	TR24465
Belt - Gen. ....	10A9733	7330
<b>Minneapolis-Moline 4-Cyl. 336 Diesel</b>		
1970-1966		
Belt - Alt. ....	10A22226	▲9463HD
Belt - Alt. & P.S. ....	10A29339	7455
Belt - Fan .....	10A9870	TR24465
Belt - Gen. ....	10A9733	7330
<b>Motrac Crawler</b>		
<b>Minneapolis-Moline 4-Cyl. 206</b>		
1962-1960		
Belt - Fan & Gen. ....		Ⓣ7470
<b>Minneapolis-Moline 4-Cyl. 206 Diesel</b>		
1961-1960		
Belt - Fan & Gen. ....		Ⓣ7470
<b>NTX</b>		
<b>Minneapolis-Moline 4-Cyl. 165</b>		
1944-1943		
Belt - Fan & W.P. ....	RE684	TR24476
Belt - Gen. ....	KE1112	▲9335HD
<b>R</b>		
<b>Hercules 4-Cyl. 165</b>		
1951		
Belt - Fan & W.P. ....	RE684	TR24476
Belt - Gen. ....	KE1112	▲9335HD
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>RH; RT</b>		
<b>Minneapolis-Moline 4-Cyl. 165</b>		
1949-1939		
Belt - Fan & W.P. ....	RE684	TR24476
Belt - Gen. ....	KE1112	▲9335HD

Application	OEM No.	Our No.
<b>MINNEAPOLIS-MOLINE - Continued</b>		
<b>RH; RT - Continued</b>		
<b>Minneapolis-Moline 4-Cyl. 165 - Continued</b>		
1949-1939 - Continued		
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>RTE</b>		
<b>Minneapolis-Moline 4-Cyl. 165</b>		
1953-1948		
Belt - Fan & W.P. ....	RE684	TR24476
Belt - Gen. ....	KE1112	▲9335HD
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>RTI; RTI-M</b>		
<b>Minneapolis-Moline 4-Cyl. 165</b>		
1955-1948		
Belt - Fan & W.P. ....	RE684	TR24476
Belt - Gen. ....	KE1112	▲9335HD
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>RTN</b>		
<b>Minneapolis-Moline 4-Cyl. 165</b>		
1951-1948		
Belt - Fan & W.P. ....	RE684	TR24476
Belt - Gen. ....	KE1112	▲9335HD
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>RTS</b>		
<b>Minneapolis-Moline 4-Cyl. 165</b>		
1953-1949		
Belt - Fan & W.P. ....	RE684	TR24476
Belt - Gen. ....	KE1112	▲9335HD
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>RTU</b>		
<b>Minneapolis-Moline 4-Cyl. 165</b>		
1954-1948		
Belt - Fan & W.P. ....	RE684	TR24476
Belt - Gen. ....	KE1112	▲9335HD
Hose - Upper .....		24224
Hose - Lower .....		24224
<b>U</b>		
<b>Minneapolis-Moline 4-Cyl. 283</b>		
1949-1938		
Belt - Gen.; Eng. No. 01905452 & Before ....	KE1112	▲9335HD
Belt - Gen.; Eng. No. 01905453 & After .....	10A1934	▲9360HD
<b>U302</b>		
<b>Minneapolis-Moline 4-Cyl. 221</b>		
1965-1964		
Belt - Fan & Alt.; W/50 5/8" Belt O.C.; Ser. No. 27601301 & After .....	10A22613	7508
Belt - Fan & Alt.; W/51 5/8" Belt O.C.; Ser. No. 27601301 & After .....	10A26150	7516
Belt - Fan & Gen.; Ser. No. 27600300 & Before .....	10A7486	7508
Belt - Fan & Gen.; Ser. No. 27600301 Thru 27601300 .....	10A16422	7490
Belt - P.S.; W/47 1/4" Belt O.C. ....	35A6148	▲9470HD
Hose - Lower .....		●25480
<b>Minneapolis-Moline 4-Cyl. 236 Diesel</b>		
1965-1964		
Belt - Fan & Alt. ....	10A26150	7516
<b>UB Special</b>		
<b>Minneapolis-Moline 4-Cyl. 283</b>		
1955		
Belt - Fan .....	10A6832	TR32491

ⓉTwo Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MINNEAPOLIS-MOLINE - Continued</b>		
<b>UB Special – Continued</b>		
<b>Minneapolis-Moline 4-Cyl. 283 – Continued</b>		
1955 – Continued		
Belt - Gen. ....	10A1934	▲9360HD
Hose - Upper .....		24226
Hose - Lower .....		24226
<b>UBD Special</b>		
<b>Minneapolis-Moline 4-Cyl. 283 Diesel</b>		
1957-1955		
Belt - Fan .....	10A6832	TR32491
Belt - Gen. ....	10A1934	▲9360HD
Hose - Lower .....		24232
<b>UBE</b>		
<b>Minneapolis-Moline 4-Cyl. 283</b>		
1955-1953		
Hose - Upper .....		24226
Hose - Lower .....		24226
<b>Minneapolis-Moline 4-Cyl. 283 Diesel</b>		
1955-1954		
Hose - Lower .....		24232
<b>UBG</b>		
<b>Minneapolis-Moline 4-Cyl. 283</b>		
1961-1953		
Hose - Upper .....		24226
Hose - Lower .....		24226
<b>UBN</b>		
<b>Minneapolis-Moline 4-Cyl. 283</b>		
1955-1953		
Hose - Upper .....		24226
Hose - Lower .....		24226
<b>Minneapolis-Moline 4-Cyl. 283 Diesel</b>		
1955-1953		
Hose - Lower .....		24232
<b>UBU</b>		
<b>Minneapolis-Moline 4-Cyl. 283</b>		
1955-1953		
Hose - Upper .....		24226
Hose - Lower .....		24226
<b>Minneapolis-Moline 4-Cyl. 283 Diesel</b>		
1955-1954		
Hose - Lower .....		24232
<b>UDS</b>		
<b>Minneapolis-Moline 4-Cyl. 283 Diesel</b>		
1961-1952		
Belt - Fan .....	KE964E	TR30467
Belt - Gen. ....	10A3995	7360
Hose - Lower .....		24232
<b>UDU</b>		
<b>Minneapolis-Moline 4-Cyl. 283 Diesel</b>		
1953-1952		
Belt - Fan .....	KE964E	TR30467
Belt - Gen. ....	10A3995	7360
Hose - Lower .....		24232
<b>Unitractor</b>		
<b>Minneapolis-Moline 4-Cyl. 283</b>		
1963-1951		
Belt - Fan .....		7320
Belt - W.P. & Gen. ....	10A7486	7508
Hose - Upper .....		24224
Hose - Lower .....		●25472

●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>MINNEAPOLIS-MOLINE - Continued</b>		
<b>UT</b>		
<b>Minneapolis-Moline 4-Cyl. 283</b>		
1959-1938		
Belt - Gen.; Eng. No. 01905452 & Before ....	KE1112	▲9335HD
Belt - Gen.; Eng. No. 01905453 & After .....	10A1934	▲9360HD
<b>UTS</b>		
<b>Minneapolis-Moline 4-Cyl. 283</b>		
1957-1948		
Belt - Fan .....	KE964E	TR30467
Belt - Gen. ....	10A1934	▲9360HD
Hose - Upper .....		24226
Hose - Lower .....		24226
<b>UTSD</b>		
<b>Minneapolis-Moline 4-Cyl. 283 Diesel</b>		
1961-1952		
Belt - Fan .....	KE964E	TR30467
Belt - Gen. ....	10A3995	7360
Hose - Lower .....		24232
<b>V</b>		
<b>Hercules 4-Cyl. 65</b>		
1953-1947		
Belt - Fan & Gen. ....	VT407	TR26353
<b>Z</b>		
<b>Minneapolis-Moline 4-Cyl. 206</b>		
1956-1946		
Belt - Fan & W.P. ....	RE684	TR24476
Belt - Gen. ....	KE1112	▲9335HD
<b>MITSUBISHI-SATOH</b>		
<b>Beaver 3</b>		
<b>Mitsubishi 3-Cyl. 47 Diesel</b>		
1984-1980		
Belt - Fan & Alt. ....		7375
<b>Bison</b>		
<b>Mazda 4-Cyl. 60</b>		
1983-1977		
Belt - Fan & Alt. ....		7390
Hose - Upper .....		●25251
<b>Buck</b>		
<b>Mitsubishi 3-Cyl. 52 Diesel</b>		
1989-1978		
Belt - Fan & Alt. ....		7320
<b>Bull</b>		
<b>Mitsubishi 2-Cyl. 76 Diesel</b>		
1989-1978		
Belt - Fan & Alt. ....		7390
<b>MT180</b>		
<b>Mitsubishi 3-Cyl. 55 Diesel</b>		
1991-1984		
Belt - Fan & Alt. ....	MD007528	7370
<b>MT210</b>		
<b>Mitsubishi 3-Cyl. 60 Diesel</b>		
1991-1984		
Belt - Fan & Alt. ....	MD007528	7370
Hose - Upper .....		●25250
<b>MT300</b>		
<b>Mitsubishi 3-Cyl. 91 Diesel</b>		
1991-1984		
Hose - Upper .....		●25250
Hose - Lower .....		●25252

Agricultural Equipment



Application	OEM No.	Our No.
<b>MITSUBISHI-SATOH - Continued</b>		
<b>MT372</b>		
Mitsubishi 2-Cyl. 41 Diesel		
1989-1981		
Belt - Fan & Alt. ....	MD030768	7345
Hose - Lower .....		●25251
<b>MT4501</b>		
Mitsubishi 4-Cyl. 127 Diesel		
1991-1985		
Belt - Fan & Alt. ....		▲9415HD
Hose - Upper .....		●25477
<b>R1500</b>		
Mitsubishi SDT75 Diesel		
1972		
Belt - Fan & Gen. ....	K7974241	▲9420HD
<b>R2500</b>		
Mitsubishi 2-Cyl. 73 Diesel		
1972		
Belt - Fan & Gen. ....	K7974241	▲9420HD
Hose - Upper .....		●26603
<b>S550G</b>		
Mazda 4-Cyl. 60		
1974-1970		
Belt - Fan & Alt. ....		7420
Belt - W.P. & Gov. ....		7410
Hose - Upper .....		●25252
Hose - Lower .....		●20476
		or ●25252
<b>S650G</b>		
Mazda 4-Cyl. 60		
1977-1972		
Belt - Fan & Alt.; W/41 1/8" Belt O.C. ....	0180190	7410
Belt - Fan & Alt.; W/41 5/8" Belt O.C. ....		7417
Belt - Fan & Alt.; W/43 1/8" Belt O.C. ....	0180200	7430
Belt - Gov.; W/41 1/8" Belt O.C. ....	0180190	7410
Belt - Gov.; W/43 5/8" Belt O.C. ....	0180200	7430
<b>Stallion</b>		
Isuzu 3-Cyl. 108 Diesel		
1984-1977		
Belt - Fan & Alt. ....	4136713030	▲9412HD
Hose - Upper .....		●25252

②Two Required ☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Application	OEM No.	Our No.
<b>MONTANA TRACTORS - Continued</b>		
<b>3840</b>		
Mitsubishi 4-Cyl. 110 Diesel		
2009-2008		
Belt - Fan .....	MD041704	7380
<b>R2844</b>		
Mitsubishi 4-Cyl. 92 Diesel		
2009		
Belt - Fan .....	MD041704	7380
2008-2006		
Belt - Fan .....		7380
<b>R3644</b>		
Mitsubishi 4-Cyl. 107 Diesel		
2009-2006		
Belt - Fan .....	MD041704	7380
<b>T2334</b>		
Mitsubishi 3-Cyl. 69 Diesel		
2008-2006		
Belt - Fan .....		7380
<b>M-R-S</b>		
<b>A80</b>		
GM 2-Cyl. 284 Diesel		
1970-1964		
Belt - Alt. ....		TR22363
Belt - Fan .....	3224368	TR34545
Hose - Upper .....		●26512
Hose - Lower .....		●26512
<b>MUIR-HILL</b>		
<b>110</b>		
Perkins 6-Cyl. 354 Diesel		
1973-1971		
Belt - Fan & Alt. ....		▲9520HD
Hose - Upper .....		●26511
<b>MULLER</b>		
<b>TM310</b>		
Cummins 6-Cyl. 855 Diesel		
1993-1990		
Belt - A.C. ....		▲9415HD
Belt - Alt. ....		②▲9510HD
Belt - Fan .....		②TR28454
Belt - W.P. ....		②7430
<b>NEW HOLLAND</b>		
<b>45; 55</b>		
New Holland 4-Cyl. 135 Diesel		
2011-2010		
Belt - Fan .....	301525A1	▲9370HD
<b>75</b>		
New Holland 4-Cyl. 195 Diesel		
2011-2010		
Belt - Serpentine .....	87705737	▲K080550HD
<b>9030</b>		
Ford 4-Cyl. 268 Diesel		
1996-1991		
Belt - A.C. ....		▲9425HD
Belt - Fan & Alt. ....	9700204	▲9570HD

Agricultural Equipment





Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>9184</b>		
<b>Cummins 6-Cyl. 505 Diesel</b>		
2001-2000		
Belt - A.C. ....	86013676	♣9476HD
<b>9280</b>		
<b>Cummins 6-Cyl. 611 Diesel</b>		
1996		
Belt - A.C. ....	9706589	♣9530HD
Belt - Alt. ....	103579	♣K050340HD
Belt - Fan ....	86001157	♣K080485HD
1995		
Belt - A.C.; Feb. 1, 1995 & Newer .....	86514599	♣9390HD
Belt - A.C.; Jan. 31, 1995 & Older .....	9706589	♣9530HD
Belt - Alt. ....	103579	♣K050340HD
Belt - Fan ....	86001157	♣K080485HD
1994		
Belt - A.C. ....	9706589	♣9530HD
Belt - Alt. ....	103579	♣K050340HD
Belt - Fan ....	86001157	♣K080485HD
<b>9282</b>		
<b>Cummins 6-Cyl. 505 Diesel</b>		
1999-1996		
Belt - A.C. ....	86013676	♣9476HD
<b>9384</b>		
<b>Cummins M11 Diesel</b>		
2001-2000		
Belt - A.C. ....	86514599	♣9390HD
Belt - Alt. ....	103579	♣K050340HD
<b>9480</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1996-1994		
Belt - A.C. ....	86514599	♣9390HD
Belt - Alt. ....	9707244	②♣9451HD
Belt - Fan ....	86514991	②TR28437
Belt - W.P. ....	86514607	♣K060435HD
<b>9482</b>		
<b>Cummins M11 Diesel</b>		
1999-1996		
Belt - A.C. ....	86514599	♣9390HD
Belt - Alt. ....	103579	♣K050340HD
<b>9484</b>		
<b>Cummins M11 Diesel</b>		
2001-2000		
Belt - A.C. ....		♣9390HD
Belt - Alt. ....		♣K050345HD
<b>9680</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1996-1994		
Belt - A.C. ....	86514599	♣9390HD
Belt - Alt. ....	9707244	②♣9451HD
Belt - Fan ....	86514991	②TR28437
Belt - W.P. ....	86514607	♣K060435HD
<b>9682</b>		
<b>Cummins N14 Diesel</b>		
1999		
Belt - A.C. ....	86514599	♣9390HD
Belt - W.P. ....	86514607	♣K060435HD
1998		
Belt - A.C. ....	86514599	♣9390HD
Belt - Alt.; Sept. 7, 1998 & Older .....	9707244	②♣9451HD
Belt - Fan; Sept. 7, 1998 & Older .....	86514991	②TR28437
Belt - W.P. ....	86514607	♣K060435HD
1997-1996		
Belt - A.C. ....	86514599	♣9390HD

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>9682 - Continued</b>		
<b>Cummins N14 Diesel - Continued</b>		
1997-1996 - Continued		
Belt - Alt. ....	9707244	②♣9451HD
Belt - Fan ....	86514991	②TR28437
Belt - W.P. ....	86514607	♣K060435HD
<b>9684</b>		
<b>Cummins N14 Diesel</b>		
2001-2000		
Belt - W.P. ....	86514607	♣K060435HD
<b>9880</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1996-1994		
Belt - A.C. ....	86514599	♣9390HD
Belt - Alt. ....	9707244	②♣9451HD
Belt - Fan ....	86514991	②TR28437
Belt - W.P. ....	86514607	♣K060435HD
<b>9882</b>		
<b>Cummins N14 Diesel</b>		
1999		
Belt - A.C. ....	86514599	♣9390HD
Belt - W.P. ....	86514607	♣K060435HD
1998		
Belt - A.C. ....	86514599	♣9390HD
Belt - Alt.; Sept. 7, 1998 & Older .....	9707244	②♣9451HD
Belt - Fan; Sept. 7, 1998 & Older .....	86514991	②TR28437
Belt - W.P. ....	86514607	♣K060435HD
1997-1996		
Belt - A.C. ....	86514599	♣9390HD
Belt - Alt. ....	9707244	②♣9451HD
Belt - Fan ....	86514991	②TR28437
Belt - W.P. ....	86514607	♣K060435HD
<b>T4.75</b>		
<b>Fiat 4-Cyl. 195 Diesel</b>		
2013-2011		
Belt - Serpentine .....	87705737	♣K080550HD
<b>Fiat 4-Cyl. 207 Diesel</b>		
2014		
Belt - Serpentine .....	87705737	♣K080550HD
<b>T6.140; T6.150</b>		
<b>New Holland 4-Cyl. 274 Diesel</b>		
2013-2011		
Belt - Fan .....	J911572	♣K080610HD
<b>T6.155</b>		
<b>New Holland 6-Cyl. 411 Diesel</b>		
2013-2011		
Belt - Fan .....	J911572	♣K080610HD
<b>T6.160</b>		
<b>New Holland 4-Cyl. 274 Diesel</b>		
2013-2011		
Belt - Fan .....	J911572	♣K080610HD
<b>T6.165; T6.175</b>		
<b>New Holland 6-Cyl. 411 Diesel</b>		
2013-2011		
Belt - Fan .....	J911572	♣K080610HD

②Two Required ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>T7.170</b>		
New Holland 6-Cyl. 411 Diesel		
2013-2011		
Belt - Fan .....	243373A1	♣K080675HD
<b>T7.175</b>		
New Holland 6-Cyl. 411 Diesel		
2014		
Belt - Fan .....	243373A1	♣K080675HD
<b>T7.185</b>		
New Holland 6-Cyl. 411 Diesel		
2013-2011		
Belt - Fan .....	243373A1	♣K080675HD
<b>T7.190</b>		
New Holland 6-Cyl. 411 Diesel		
2014		
Belt - Fan .....	243373A1	♣K080675HD
<b>T7.200</b>		
New Holland 6-Cyl. 411 Diesel		
2013-2011		
Belt - Fan .....	243373A1	♣K080675HD
<b>T7.210</b>		
New Holland 6-Cyl. 411 Diesel		
2014-2011		
Belt - Fan .....	243373A1	♣K080675HD
<b>T1510</b>		
New Holland 3-Cyl. 91 Diesel		
2011-2008		
Belt - Fan .....	301525A1	♣9370HD
<b>T1520</b>		
New Holland 3-Cyl. 101 Diesel		
2011-2007		
Belt - Fan .....	301525A1	♣9370HD
<b>T1530</b>		
New Holland 4-Cyl. 135 Diesel		
2011-2009		
Belt - Fan .....	301525A1	♣9370HD
<b>T4020; T4030</b>		
New Holland 4-Cyl. 195 Diesel		
2013-2008		
Belt - Serpentine .....	87705737	♣K080550HD
<b>T4040</b>		
New Holland 4-Cyl. 274 Diesel		
2013-2008		
Belt - Serpentine; W/Cab .....	47131754	♣K080545HD
Belt - Serpentine; W/O Cab .....	J911587	♣K080537HD
<b>T4040V</b>		
New Holland 4-Cyl. 195 Diesel		
2011-2008		
Belt - Serpentine .....	47131754	♣K080545HD
<b>T4050</b>		
New Holland 4-Cyl. 274 Diesel		
2013-2008		
Belt - Serpentine; W/Cab .....	47131754	♣K080545HD
Belt - Serpentine; W/O Cab .....	J911587	♣K080537HD
<b>T5040; T5050; T5060; T5070</b>		
New Holland 4-Cyl. 274 Diesel		
2011-2008		
Belt - Serpentine; W/Cab .....	47131754	♣K080545HD

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>T5040; T5050; T5060; T5070 - Continued</b>		
New Holland 4-Cyl. 274 Diesel - Continued		
2011-2008 - Continued		
Belt - Serpentine; W/O Cab .....	J911587	♣K080537HD
<b>T6020</b>		
New Holland 4-Cyl. 274 Diesel		
2011-2010		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. Z9BD09539 & Before ...	J911572	♣K080610HD
Belt - Fan; Ser. No. Z9BD09540 & After .....	J911563	♣K080605HD
Tensioner Assy. ....	2855622	38639
2009-2007		
Belt - A.C. ....	87802911	K040390
Belt - Fan; Ser. No. Z9BD09539 & Before ...	J911572	♣K080610HD
Belt - Fan; Ser. No. Z9BD09540 & After .....	J911563	♣K080605HD
Belt - Fan & Alt. ....	4899178	♣K080610HD
Tensioner Assy. ....	2855622	38639
<b>T6030</b>		
New Holland 6-Cyl. 411 Diesel		
2011-2007		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. Z9BD09539 & Before ...	J911572	♣K080610HD
Belt - Fan; Ser. No. Z9BD09540 & After .....	J911563	♣K080605HD
Tensioner Assy. ....	2855622	38639
<b>T6040</b>		
New Holland 4-Cyl. 274 Diesel		
2011-2007		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. Z9BD09539 & Before ...	J911572	♣K080610HD
Belt - Fan; Ser. No. Z9BD09540 & After .....	J911563	♣K080605HD
Tensioner Assy. ....	2855622	38639
<b>T6050</b>		
New Holland 6-Cyl. 411 Diesel		
2011-2007		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. Z9BD09539 & Before ...	J911572	♣K080610HD
Belt - Fan; Ser. No. Z9BD09540 & After .....	J911563	♣K080605HD
Tensioner Assy. ....	2855622	38639
<b>T6060</b>		
New Holland 4-Cyl. 274 Diesel		
2011-2007		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. Z9BD09539 & Before ...	J911572	♣K080610HD
Belt - Fan; Ser. No. Z9BD09540 & After .....	J911563	♣K080605HD
Tensioner Assy. ....	2855622	38639
<b>T6070</b>		
New Holland 6-Cyl. 411 Diesel		
2012-2007		
Belt - A.C. ....	87710661	♣K040388HD
Belt - Fan; Ser. No. Z9BD09539 & Before ...	J911572	♣K080610HD
Belt - Fan; Ser. No. Z9BD09540 & After .....	J911563	♣K080605HD
Tensioner Assy. ....	2855622	38639
<b>TB100</b>		
Genesis 4-Cyl. 304 Diesel		
2008-2003		
Belt - Alt. ....		A30
Belt - P.S. ....		A44
<b>TB120</b>		
Genesis 6-Cyl. 456 Diesel		
2006-2004		
Belt - Alt. ....		A30
Belt - P.S. ....		A44

♣Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TC18</b>		
<b>Shibaura 3-Cyl. 58 Diesel</b>		
2003-1998		
Belt - Fan & Alt. ....	SBA080109049	7300
<b>TC21</b>		
<b>New Holland 3-Cyl. 61 Diesel</b>		
2005-2004		
Belt - Fan & Alt. ....	SBA080109049	7300
<b>Shibaura 3-Cyl. 61 Diesel</b>		
2003-1999		
Belt - Fan & Alt. ....		7300
<b>TC23</b>		
<b>New Holland 3-Cyl. 61 Diesel</b>		
2007-2005		
Belt - Fan & Alt. ....	SBA080109049	7300
<b>TC24</b>		
<b>New Holland 3-Cyl. 69 Diesel</b>		
2005-2004		
Belt - Fan & Alt. ....	SBA080109049	7300
<b>Shibaura 3-Cyl. 69 Diesel</b>		
2003-2002		
Belt - Fan & Alt. ....		7350
<b>TC25</b>		
<b>Shibaura 3-Cyl. 81 Diesel</b>		
2002-1999		
Belt - Fan & Alt. ....		AX35
<b>TC26</b>		
<b>New Holland 3-Cyl. 69 Diesel</b>		
2007-2005		
Belt - Fan & Alt. ....	SBA080109049	7300
<b>TC29</b>		
<b>New Holland 3-Cyl. 81 Diesel</b>		
2006-2004		
Belt - Fan & Alt. ....	86517954	AX36
<b>Shibaura 3-Cyl. 81 Diesel</b>		
2003-1998		
Belt - Fan & Alt. ....		AX35
<b>TC30</b>		
<b>Shibaura 3-Cyl. 91 Diesel</b>		
2007-2001		
Belt - Fan & Alt. ....		7350
<b>TC31</b>		
<b>New Holland 3-Cyl. 91 Diesel</b>		
2007-2006		
Belt - Fan & Alt. ....	86517954	AX36
<b>TC33</b>		
<b>New Holland 3-Cyl. 91 Diesel</b>		
2007-2004		
Belt - Fan & Alt. ....	86517954	AX36
<b>Shibaura 3-Cyl. 91 Diesel</b>		
2003-1998		
Belt - Fan & Alt. ....		7350

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TC34</b>		
<b>New Holland 3-Cyl. 101 Diesel</b>		
2006		
Belt - Fan & Alt. ....	86517954	AX36
<b>TC35</b>		
<b>New Holland 3-Cyl. 101 Diesel</b>		
2007-2004		
Belt - Fan & Alt. ....	301525A1	♣9370HD
<b>Shibaura 3-Cyl. 101 Diesel</b>		
2003-2002		
Belt - Fan & Alt. ....		7350
2001-2000		
Belt - Fan & Alt. ....		7530
<b>TC40</b>		
<b>New Holland 4-Cyl. 122 Diesel</b>		
2007-2004		
Belt - A.C. ....	86401123	AX45
Belt - Fan & Alt. ....	301525A1	♣9370HD
<b>Shibaura 4-Cyl. 122 Diesel</b>		
2003-2002		
Belt - Fan To Alt. ....		7350
2001-2000		
Belt - Fan & Alt. ....		7350
<b>TC45</b>		
<b>New Holland 4-Cyl. 135 Diesel</b>		
2007-2004		
Belt - Fan & Alt. ....		♣9370HD
<b>Shibaura 4-Cyl. 135 Diesel</b>		
2003-2000		
Belt - Fan & Alt. ....		7350
<b>TC48; TC55</b>		
<b>New Holland 4-Cyl. 135 Diesel</b>		
2007-2004		
Belt - Fan & Alt. ....	86517954	AX36
<b>TD95D</b>		
<b>New Holland 4-Cyl. 238 Diesel</b>		
2008-2007		
Belt - A.C. ....	5094418	7410
Belt - Fan ....	98473706	7453
<b>TD4040</b>		
<b>New Holland 4-Cyl. 195 Diesel</b>		
2014-2013		
Belt - Serpentine ....	47131754	♣K080545HD
<b>TG210</b>		
<b>New Holland 6-Cyl. 505 Diesel</b>		
2006-2002		
Belt - Fan & W.P. ....	87403144	♣K080859HD
<b>TG215</b>		
<b>New Holland 6-Cyl. 505 Diesel</b>		
2008-2006		
Belt - Fan & W.P.; W/11-Blade Fan ....	87441272	♣K080865HD
Belt - Fan & W.P.; W/8-Blade Fan ....	87441270	♣K080876HD
<b>TG230</b>		
<b>New Holland 6-Cyl. 505 Diesel</b>		
2006-2002		
Belt - Fan & W.P. ....	87403144	♣K080859HD

♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TG245</b>		
New Holland 6-Cyl. 505 Diesel		
2008-2006		
Belt - Fan & W.P.; W/11-Blade Fan .....	87441272	♣K080865HD
Belt - Fan & W.P.; W/8-Blade Fan .....	87441270	♣K080876HD
<b>TG255</b>		
New Holland 6-Cyl. 505 Diesel		
2006-2002		
Belt - Fan & W.P. ....	87403145	♣K080850HD
<b>TG275</b>		
New Holland 6-Cyl. 505 Diesel		
2008-2006		
Belt - Fan & W.P.; W/11-Blade Fan .....	87441272	♣K080865HD
Belt - Fan & W.P.; W/8-Blade Fan .....	87441270	♣K080876HD
<b>TG285</b>		
New Holland 6-Cyl. 505 Diesel		
2006-2002		
Belt - Fan & W.P. ....	87403145	♣K080850HD
<b>TG305</b>		
New Holland 6-Cyl. 505 Diesel		
2008-2006		
Belt - Fan & W.P.; W/11-Blade Fan .....	87441272	♣K080865HD
Belt - Fan & W.P.; W/8-Blade Fan .....	87441270	♣K080876HD
<b>TJ275</b>		
New Holland 6-Cyl. 505 Diesel		
2006-2002		
Belt - Fan & Alt. ....	87443440	♣K080670HD
Tensioner Assy. - Fan & Alt. ....	87326910	38504
<b>TJ280</b>		
New Holland 6-Cyl. 505 Diesel		
2008-2006		
Belt - A.C. ....	A189040	♣9463HD
Belt - Fan & W.P. ....	87363088	♣K080675HD
Tensioner Assy. ....	87436755	38516
<b>TJ325</b>		
New Holland 6-Cyl. 543 Diesel		
2005-2002		
Belt - Fan & Alt. ....	87443440	♣K080670HD
Tensioner Assy. - Fan & Alt. ....	87326910	38504
<b>TJ330</b>		
New Holland 6-Cyl. 543 Diesel		
2008-2006		
Belt - W.P. ....	87363088	♣K080675HD
Tensioner Assy. - W.P. ....	87436755	38516
<b>TJ380</b>		
New Holland 6-Cyl. 787 Diesel		
2008-2006		
Belt - Fan & Alt. ....	504078066	♣K080991HD
<b>TJ430</b>		
New Holland 6-Cyl. 787 Diesel		
2008-2006		
Belt - W.P., Alt. & A.C. ....	87282333	♣K080991HD
<b>TJ480; TJ530</b>		
Cummins 6-Cyl. 915 Diesel		
2008-2006		
Belt - Alt. & A.C. ....	87366407	♣K060635HD

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TK76</b>		
New Holland 4-Cyl. 220 Diesel		
2003-2001		
Belt - Fan & Alt. ....	98473705	7465
<b>TK80</b>		
New Holland 4-Cyl. 220 Diesel		
2006-2004		
Belt - Fan & Alt. ....	98473705	7465
<b>TK85</b>		
New Holland 4-Cyl. 238 Diesel		
2003-2001		
Belt - Fan & Alt. ....	98473705	7465
<b>TK90A</b>		
New Holland 4-Cyl. 238 Diesel		
2008-2006		
Belt - A.C. ....	5154152	♣9345HD
Belt - Fan & Alt. ....	98473705	7465
<b>TK100A</b>		
New Holland 4-Cyl. 238 Diesel		
2008-2004		
Belt - Fan & Alt. ....	98473705	7465
<b>TK4030V</b>		
New Holland 4-Cyl. 195 Diesel		
2014-2009		
Belt - Serpentine; W/Cab .....	47131754	♣K080545HD
Belt - Serpentine; W/O Cab .....	87705737	♣K080550HD
<b>TK4050; TK4060</b>		
New Holland 4-Cyl. 274 Diesel		
2014-2009		
Belt - Serpentine; W/Cab .....	J911587	♣K080537HD
Belt - Serpentine; W/O Cab .....	47131754	♣K080545HD
<b>TL100</b>		
Iveco 4-Cyl. 238 Diesel		
2003-1999		
Belt - Fan & Alt.; W/85A. Alt. ....	500369112	7460
Belt - Fan & Alt.; W/O 85A. Alt. ....	98473705	7465
<b>TL100A</b>		
New Holland 4-Cyl. 273 Diesel		
2008-2004		
Belt - A.C. ....	47129821	♣9412HD
Belt - Fan & Alt.; W/O Fan Clutch .....	47131754	♣K080545HD
Belt - Fan & Alt.; W/Viscous Fan Clutch .....	47135840	♣K080537HD
<b>TM115</b>		
New Holland 6-Cyl. 456 Diesel		
2002-2000		
Belt - Fan & Alt.; W/A.C. ....	87800858	♣K080774HD
Belt - Fan & Alt.; W/O A.C. ....	87840341	♣K080580HD
<b>TM120</b>		
New Holland 6-Cyl. 456 Diesel		
2008-2002		
Belt - Fan, Alt. & A.C. ....	87802822	♣K080806HD
<b>TM125</b>		
New Holland 6-Cyl. 456 Diesel		
2002-2000		
Belt - Fan & Alt.; W/A.C. ....	87800858	♣K080774HD
Belt - Fan & Alt.; W/O A.C. ....	87840341	♣K080580HD

♣Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TM130</b>		
<b>New Holland 6-Cyl. 456 Diesel</b>		
2008-2002		
Belt - Fan, Alt. & A.C. ....	87802822	♣K080806HD
<b>TM135</b>		
<b>New Holland 6-Cyl. 456 Diesel</b>		
2002-2000		
Belt - Fan & Alt.; W/A.C. ....	87800858	♣K080774HD
Belt - Fan & Alt.; W/O A.C. ....	87840341	♣K080580HD
<b>TM140</b>		
<b>New Holland 6-Cyl. 456 Diesel</b>		
2008-2002		
Belt - Fan, Alt. & A.C. ....	87802822	♣K080806HD
<b>TM150</b>		
<b>New Holland 6-Cyl. 456 Diesel</b>		
2002-2000		
Belt - Fan & Alt.; W/A.C. ....	87800858	♣K080774HD
Belt - Fan & Alt.; W/O A.C. ....	87840341	♣K080580HD
<b>TM155</b>		
<b>New Holland 6-Cyl. 456 Diesel</b>		
2008-2002		
Belt - Serpentine ....	87802822	♣K080806HD
<b>TM165</b>		
<b>New Holland 6-Cyl. 456 Diesel</b>		
2002-2000		
Belt - Fan & Alt.; W/A.C. ....	87800858	♣K080774HD
Belt - Fan & Alt.; W/O A.C. ....	87840341	♣K080580HD
<b>TM175</b>		
<b>New Holland 6-Cyl. 456 Diesel</b>		
2008-2002		
Belt - Serpentine ....	87802822	♣K080806HD
<b>TM190</b>		
<b>New Holland 6-Cyl. 456 Diesel</b>		
2008-2005		
Belt - Serpentine ....	87802822	♣K080806HD
2004-2002		
Belt - W.P., Alt. & A.C. ....	87802822	♣K080806HD
<b>TN55</b>		
<b>Iveco 3-Cyl. 179 Diesel</b>		
2003-1999		
Belt - Fan & Alt. ....	98473705	7465
<b>TN60A; TN60DA</b>		
<b>New Holland 3-Cyl. 179 Diesel</b>		
2008-2004		
Belt - Fan & Alt. ....	98473705	7465
<b>TN65</b>		
<b>Iveco 3-Cyl. 179 Diesel</b>		
2003-1999		
Belt - Fan & Alt. ....	98473705	7465
<b>TN65F</b>		
<b>Iveco 4-Cyl. 238 Diesel</b>		
2003-1998		
Belt - A.C. ....	5154152	♣9345HD
Belt - Fan & Alt. ....	98473705	7465

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TN70</b>		
<b>Iveco 3-Cyl. 179 Diesel</b>		
2004-2000		
Belt - Fan & Alt. ....	98473705	7465
<b>TN70A</b>		
<b>New Holland 3-Cyl. 179 Diesel</b>		
2005-2004		
Belt - Fan & Alt. ....	98473705	7465
<b>TN70DA</b>		
<b>New Holland 3-Cyl. 179 Diesel</b>		
2008-2004		
Belt - Fan & Alt. ....	98473705	7465
<b>TN70F</b>		
<b>New Holland 4-Cyl. 238 Diesel</b>		
2005-2003		
Belt - A.C. ....	5154152	♣9345HD
Belt - Fan & Alt. ....	98473705	7465
<b>TN75</b>		
<b>Iveco 3-Cyl. 179 Diesel</b>		
2003-1999		
Belt - Fan & Alt. ....	98473705	7465
<b>TN75A; TN75DA</b>		
<b>New Holland 3-Cyl. 179 Diesel</b>		
2008-2004		
Belt - Fan & Alt. ....	98473705	7465
<b>TN75F</b>		
<b>Iveco 4-Cyl. 238 Diesel</b>		
2003-1998		
Belt - A.C. ....	5154152	♣9345HD
Belt - Fan & Alt. ....	98473705	7465
<b>TN75FA</b>		
<b>New Holland 4-Cyl. 238 Diesel</b>		
2008-2004		
Belt - A.C. ....	5154152	♣9345HD
Belt - Fan & Alt. ....	98473705	7465
<b>TN75SA; TN75VA</b>		
<b>New Holland 3-Cyl. 179 Diesel</b>		
2008-2004		
Belt - Fan & Alt. ....	98473705	7465
<b>TN80F</b>		
<b>New Holland 4-Cyl. 238 Diesel</b>		
2003-2002		
Belt - A.C. ....	5154152	♣9345HD
Belt - Fan & Alt. ....	98473705	7465
<b>TN85DA</b>		
<b>New Holland 4-Cyl. 274 Diesel</b>		
2008-2006		
Belt - A.C. ....	47129821	♣9412HD
Belt - Fan; W/H.D. Cool.; W/P.T.O. ....	47135840	♣K080537HD
Belt - Fan; W/O H.D. Cool.; W/O P.T.O. ....	47131754	♣K080545HD
<b>TN85FA</b>		
<b>New Holland 4-Cyl. 238 Diesel</b>		
2008-2004		
Belt - A.C. ....	5154152	♣9345HD
Belt - Fan & Alt. ....	98473705	7465
<b>TN90F</b>		
<b>Iveco 4-Cyl. 238 Diesel</b>		
2001-1998		
Belt - A.C. ....	5154152	♣9345HD

♣Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TN90F – Continued</b>		
Iveco 4-Cyl. 238 Diesel – Continued		
2001–1998 – Continued		
Belt - Fan & Alt. ....	98473705	7465
<b>TN95F</b>		
New Holland 4-Cyl. 238 Diesel		
2005–2002		
Belt - A.C. ....	5154152	♣9345HD
Belt - Fan & Alt. ....	98473705	7465
<b>TN95FA</b>		
New Holland 4-Cyl. 238 Diesel		
2008–2004		
Belt - A.C. ....	5154152	♣9345HD
Belt - Fan ....	98473705	Ⓣ7465
<b>TN95VA</b>		
New Holland 4-Cyl. 238 Diesel		
2008–2005		
Belt - A.C. ....	5154152	♣9345HD
Belt - Fan ....	98473705	Ⓣ7465
<b>TS90; TS100</b>		
Genesis 4-Cyl. 304 Diesel		
2003–1998		
Belt - Fan & Alt. ....	82850752	♣K061005HD
Tensioner Assy. ....	87801689	38672
<b>TS100A</b>		
New Holland 4-Cyl. 273 Diesel		
2008–2004		
Belt - A.C. ....	87802911	K040390
Belt - Fan & Alt. ....	4899178	♣K080610HD
<b>TS110</b>		
Genesis 4-Cyl. 304 Diesel		
2003–1998		
Belt - Fan & Alt. ....	82850752	♣K061005HD
Tensioner Assy. ....	87801689	38672
<b>TS110A</b>		
New Holland 4-Cyl. 274 Diesel		
2008–2007		
Belt - A.C. ....	87802911	K040390
Belt - Fan ....	4899178	♣K080610HD
Tensioner Assy. - Fan ....	2852161	38639
<b>TS115</b>		
Genesis 4-Cyl. 304 Diesel		
2002–2001		
Tensioner Assy. ....	87801689	38672
<b>TS115A</b>		
New Holland 6-Cyl. 410 Diesel		
2008–2004		
Belt - A.C. ....	87802911	K040390
Belt - Fan & Alt. ....	4899178	♣K080610HD
<b>TS125A</b>		
New Holland 6-Cyl. 410 Diesel		
2008–2004		
Belt - Fan & A.C. ....	87802911	K040390
Belt - Fan & Alt. ....	4899178	♣K080610HD
<b>TS135A</b>		
New Holland 6-Cyl. 410 Diesel		
2008–2004		
Belt - A.C. ....	87802911	K040390
Belt - Fan & Alt. ....	4899178	♣K080610HD

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>TT50A</b>		
New Holland 4-Cyl. 135 Diesel		
2009–2007		
Belt - Fan ....	301525A1	♣9370HD
<b>TT75</b>		
New Holland 4-Cyl. 238 Diesel		
2006–2004		
Belt - Alt. ....		7445
<b>TZ18DA; TZ22DA</b>		
New Holland 3-Cyl. 58 Diesel		
2008–2004		
Belt - Fan ....	SBA080109049	7300
<b>TZ24DA</b>		
New Holland 3-Cyl. 61 Diesel		
2006–2004		
Belt - Fan ....	SBA080109049	7300
<b>TZ25DA</b>		
New Holland 3-Cyl. 61 Diesel		
2008–2004		
Belt - Fan & Alt. ....	224354	7300
<b>Workmaster 45; Workmaster 55</b>		
Shibaura 4-Cyl. 135 Diesel		
2014–2009		
Belt - Fan ....	301525A1	♣9370HD
<b>Workmaster 75</b>		
New Holland 4-Cyl. 195 Diesel		
2014–2010		
Belt - Serpentine ....	87705737	♣K080550HD
<b>OLIVER</b>		
<b>66</b>		
Oliver 4-Cyl. 129		
1954–1949		
Belt - Fan ....	M372	TR24365
Belt - Fan, Gen. & S.P. ....	1M372B	7435
Belt - Gen. ....	H1257	6825
Oliver 4-Cyl. 129 Diesel		
1954–1949		
Belt - Fan ....	M372	TR24365
Belt - Fan, Gen. & S.P. ....	1M372B	7435
Belt - Gen. ....	H1257	6825
<b>77</b>		
Oliver 6-Cyl. 194		
1954–1948		
Belt - Fan ....	M372	TR24365
Belt - Gen. ....	H1257	6825
Oliver 6-Cyl. 194 Diesel		
1954–1948		
Belt - Fan ....	M372	TR24365
Belt - Gen. ....	H1257	6825
Oliver 6-Cyl. 194 LPG		
1954–1948		
Belt - Fan ....	M372	TR24365
Belt - Gen. ....	H1257	6825
<b>80</b>		
Oliver 4-Cyl. 298		
1948–1937		
Belt - Fan ....	C372A	TR30467
Belt - Gen. ....	C1257A	TR22299

ⓉTwo Required ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>80 - Continued</b>		
<b>Oliver 4-Cyl. 334 Distillate</b>		
1948-1937		
Belt - Fan .....	C372A	TR30467
Belt - Gen. ....	C1257A	TR22299
<b>88</b>		
<b>Oliver 6-Cyl. 231</b>		
1954-1947		
Belt - Fan .....	K372	TR22380
Belt - Gen. ....	H1257	6825
Hose - Upper; Molded Hose .....		●25472
Hose - Upper; Strt. Hose .....		24224
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>Oliver 6-Cyl. 231 Diesel</b>		
1954-1947		
Belt - Fan .....	K372	TR22380
Belt - Gen. ....	H1257	6825
<b>Oliver 6-Cyl. 231 LPG</b>		
1954-1947		
Belt - Fan .....	K372	TR22380
Belt - Gen. ....	H1257	6825
Hose - Upper; Molded Hose .....		●25472
Hose - Upper; Strt. Hose .....		24224
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>90</b>		
<b>Oliver 4-Cyl. 443</b>		
1952-1937		
Belt - Fan .....	A372	TR34545
<b>99</b>		
<b>Oliver 4-Cyl. 443</b>		
1956-1950		
Belt - Fan .....	K372	TR22380
Belt - Gen. ....	7A1257	9279
<b>550</b>		
<b>Oliver 4-Cyl. 155</b>		
1975-1958		
Belt - Fan & Gen.; W/O P.S.; Ser. No. 72831 & Before .....		7425
Belt - Fan & Gen.; W/O P.S.; Ser. No. 72832 & After .....		7440
Belt - Fan & Gen.; W/P.S.; Ser. No. 72831 & Before .....	1M372B	7435
Belt - Fan & Gen.; W/P.S.; Ser. No. 72832 & After .....		7450
Belt - P.S. ....		7430
Hose - Upper; Ser. No. 127364 & Before .....		≧20065
		or ●25473
Hose - Upper; Ser. No. 127365 & After .....		≧20065
		or ●25526
Hose - Lower; Ser. No. 127364 & Before .....		●25476
<b>Oliver 4-Cyl. 155 Diesel</b>		
1975-1958		
Belt - Fan & Gen.; W/O P.S.; Ser. No. 72831 & Before .....		7425
Belt - Fan & Gen.; W/O P.S.; Ser. No. 72832 & After .....		7440
Belt - Fan & Gen.; W/P.S.; Ser. No. 72831 & Before .....	1M372B	7435
Belt - Fan & Gen.; W/P.S.; Ser. No. 72832 & After .....		7450
Belt - P.S. ....		7430
Hose - Upper; Ser. No. 127365 & After .....		≧20065
		or ●25526
Hose - Upper; Ser. No. 72381 & Before .....		≧20065
		or ●25473
Hose - Upper; Ser. No. 72382 Thru 127364 .....		≧20065
		or ●25526
Hose - Lower; Ser. No. 72381 & Before .....		●25476
Hose - By Pass; Ser. No. 127364 & Before .....		24224

Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>660</b>		
<b>Oliver 4-Cyl. 155</b>		
1964-1959		
Belt - Fan & Gen. ....		7425
Belt - Fan, Gen. & S.P. ....	1M372B	7435
Hose - Upper .....		≧20267
		or ●25472
Hose - Lower .....		24224
<b>Oliver 4-Cyl. 155 Diesel</b>		
1964-1959		
Belt - Fan & Gen. ....		7425
Belt - Fan, Gen. & S.P. ....	1M372B	7435
Hose - Upper .....		≧20267
		or ●25472
Hose - Lower .....		24224
<b>770</b>		
<b>Oliver 6-Cyl. 216</b>		
1967-1958		
Belt - Fan & Gen.; W/O P.S.; Ser. No. 73639 & After .....		7430
Belt - Fan & Gen.; W/P.S.; Ser. No. 117125 & After .....		7440
Belt - Fan & Gen.; W/P.S.; Ser. No. 60501 Thru 73638 .....	1M372B	7435
Belt - Fan & Gen.; W/P.S.; Ser. No. 73639 Thru 117124 .....	1K372B	7455
Belt - P.S.; W/49 1/8" Belt O.C. ....	157538A	7490
Belt - P.S.; W/52 5/8" Belt O.C. ....	106821A	7525
Hose - Upper .....		≧20065
		or ●25473
<b>Oliver 6-Cyl. 216 Diesel</b>		
1967-1958		
Belt - Fan & Gen.; W/O P.S.; Ser. No. 73639 & After .....		7430
Belt - Fan & Gen.; W/P.S.; Ser. No. 117125 & After .....		7440
Belt - Fan & Gen.; W/P.S.; Ser. No. 60501 Thru 73638 .....	1M372B	7435
Belt - Fan & Gen.; W/P.S.; Ser. No. 73639 Thru 117124 .....	1K372B	7455
Belt - P.S.; W/49 1/8" Belt O.C. ....	157538A	7490
Belt - P.S.; W/52 5/8" Belt O.C. ....	106821A	7525
Hose - Upper .....		≧20065
		or ●25473
<b>Oliver 6-Cyl. 216 LPG</b>		
1967-1958		
Hose - Upper .....		≧20065
		or ●25472
<b>880</b>		
<b>Oliver 6-Cyl. 265</b>		
1963-1958		
Belt - Fan & Gen.; W/O P.S. ....		7430
Belt - Fan & Gen.; W/P.S.; Ser. No. 117125 & After .....		7440
Belt - Fan & Gen.; W/P.S.; Ser. No. 60501 Thru 117124 .....	1K372B	7455
Belt - P.S. ....	106821A	7525
Hose - Upper .....		≧20065
		or ●25473
Hose - Lower .....		24224
<b>Oliver 6-Cyl. 265 Diesel</b>		
1963-1958		
Belt - Fan & Gen.; W/O P.S. ....		7430
Belt - Fan & Gen.; W/P.S.; Ser. No. 117125 & After .....		7440
Belt - Fan & Gen.; W/P.S.; Ser. No. 60501 Thru 117124 .....	1K372B	7455
Belt - P.S. ....	106821A	7525
Hose - Upper .....		≧20065
		or ●25473
Hose - Lower .....		24224
<b>950</b>		
<b>Oliver 6-Cyl. 302</b>		
1961-1958		
Hose - Upper .....		≧20206
Hose - Lower .....		24236

≧Cut to Fit ●Flexible Coolant Hose



Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>950 - Continued</b>		
<b>Oliver 6-Cyl. 302 Diesel</b>		
1961-1958		
Hose - Upper .....		20206
Hose - Lower .....		24236
<b>990</b>		
<b>GM 3-Cyl. 213 Diesel</b>		
1961-1958		
Belt - Fan & Alt. ....	106355A	TR34467
Hose - Upper .....		20206
Hose - Lower .....		24236
<b>995</b>		
<b>GM 3-Cyl. 213 Diesel</b>		
1961-1958		
Belt - Fan & Alt. ....	106355A	TR34467
<b>1265</b>		
<b>Fiat 3-Cyl. 158 Diesel</b>		
1975-1971		
Belt - Fan & Alt. ....	4818920	7455
Hose - Upper .....		26508
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>1355</b>		
<b>Fiat 4-Cyl. 190 Diesel</b>		
1971-1969		
Belt - A.C. ....	9580HD	
Belt - Fan & Alt. ....	9580HD	
Hose - Upper .....		26612
Hose - Lower .....		24244
Hose - By Pass .....		24232
<b>1365</b>		
<b>Fiat 4-Cyl. 211 Diesel</b>		
1975-1971		
Belt - Fan & Alt. ....	676865A	7450
Hose - Upper .....		26603
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		20351
<b>1450</b>		
<b>Fiat 4-Cyl. 268 Diesel</b>		
1969-1967		
Belt - Fan & Alt./Gen. ....		TR22508
<b>1550</b>		
<b>Oliver 6-Cyl. 232</b>		
1969-1965		
Belt - A.C. ....		7480
Belt - Fan & Gen.; Ser. No. 160000 Thru 169844 .....	160610A	9447HD
Belt - Fan & Gen.; Ser. No. 169845 & After . 162123A .....		7445
Belt - P.S. ....	157176AA	7290
Hose - Lower - Eng. To Pipe; Ser. No. 160000 Thru 201509 ....		24228
Hose - Lower - Eng. To Pipe; Ser. No. 201501 & After .....		20520
Hose - Lower - Pipe To Rad.; Ser. No. 160000 Thru 201509 ....		24228
Hose - Lower - Pipe To Rad.; Ser. No. 201501 & After .....		24234
<b>Oliver 6-Cyl. 232 Diesel</b>		
1969-1965		
Belt - A.C. ....	167897A	7480
Belt - Fan & Gen.; Ser. No. 160000 Thru 168920 .....	160610A	9447HD
Belt - Fan & Gen.; Ser. No. 168921 & After . 158679A .....		7450
Belt - P.S. ....	157177AA	7375
Hose - Lower .....		24228
<b>Oliver 6-Cyl. 232 LPG</b>		
1969-1965		
Belt - A.C. ....	167897A	7480
Belt - Fan & Gen.; Ser. No. 160000 Thru 169386 .....	160610A	9447HD

Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>1550 - Continued</b>		
<b>Oliver 6-Cyl. 232 LPG - Continued</b>		
1969-1965 - Continued		
Belt - Fan & Gen.; Ser. No. 169387 & After .	162123A	7445
Belt - P.S. ....	157176AA	7290
<b>1555</b>		
<b>Oliver 6-Cyl. 232</b>		
1975-1969		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162123A	7445
Belt - P.S. ....	157176AA	7290
Hose - Lower - Eng. To Pipe .....		20520
Hose - Lower - Pipe To Rad. ....		24234
<b>Oliver 6-Cyl. 232 Diesel</b>		
1975-1969		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	158679A	7450
Belt - P.S. ....	157177AA	7375
Hose - Lower .....		24228
<b>1600</b>		
<b>Oliver 6-Cyl. 231</b>		
1964-1962		
Belt - Fan & Gen.; W/42 5/8" Belt O.C. ....		7425
Belt - Fan & Gen.; W/43 1/8" Belt O.C. ....		7430
Belt - P.S. ....	156096A	7500
Hose - Upper; Ser. No. 124420 Thru 137612 .....		21660
		or 25476
Hose - Upper; Ser. No. 137613 & After .....		20611
		or 26509
Hose - Lower - Eng. To Pipe .....		24228
Hose - Lower - Pipe To Rad. ....		24228
<b>Oliver 6-Cyl. 248</b>		
1964-1962		
Belt - Fan & Gen.; W/42 5/8" Belt O.C. ....		7425
Belt - Fan & Gen.; W/43 1/8" Belt O.C. ....		7430
Belt - P.S. ....	156096A	7500
Hose - Upper; Ser. No. 124420 Thru 137612 .....		21660
		or 25476
Hose - Upper; Ser. No. 137613 & After .....		20611
		or 26509
Hose - Lower - Eng. To Pipe .....		24228
Hose - Lower - Pipe To Rad. ....		24228
<b>Oliver 6-Cyl. 265 Diesel</b>		
1964-1962		
Belt - Fan & Gen.; W/42 5/8" Belt O.C. ....		7425
Belt - Fan & Gen.; W/43 1/8" Belt O.C. ....		7430
Belt - P.S. ....	156096A	7500
Hose - Upper; Ser. No. 124420 Thru 127612 .....		21256
		or 26504
Hose - Upper; Ser. No. 124420 Thru 139392 .....		21660
		or 25476
Hose - Upper; Ser. No. 139393 Thru 147568 .....		20611
		or 26509
Hose - Lower - Eng. To Pipe .....		24228
Hose - Lower - Pipe To Rad. ....		24228
<b>1650</b>		
<b>Oliver 6-Cyl. 265</b>		
1969-1964		
Belt - Fan & Alt. ....	158679A	7450
Hose - Upper; Ser. No. 124420 & After .....		24228
Hose - Upper; Ser. No. 137613 Thru 178174 .....		20611
		or 26509
Hose - Upper; Ser. No. 178175 & After .....		20611
Hose - Lower; Ser. No. 124420 & After .....		24228
Hose - Lower; Ser. No. 147569 Thru 178179 .....		24228
Hose - Lower; Ser. No. 178175 & After .....		24234
<b>Oliver 6-Cyl. 265 LPG</b>		
1969-1964		
Belt - Fan & Alt. ....	158679A	7450
Hose - Upper; Ser. No. 124420 & After .....		24228

②Two Required ③Three Required ≡Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>1650 - Continued</b>		
<b>Oliver 6-Cyl. 265 LPG - Continued</b>		
<b>1969-1964 - Continued</b>		
Hose - Upper; Ser. No. 137613 Thru 178174 .....		≠20611 or ●26509
Hose - Upper; Ser. No. 178175 & After .....		≠20611
Hose - Lower; Ser. No. 124420 & After .....		24228
Hose - Lower; Ser. No. 147569 Thru 178179 .....		24228
Hose - Lower; Ser. No. 178175 & After .....		24234
<b>Oliver 6-Cyl. 283 Diesel</b>		
<b>1969-1964</b>		
Belt - Fan & Alt.; W/Dual Belts .....	162071A	②7460
Belt - Fan & Alt.; W/Single Belt .....	157680A	7460
Belt - P.S. ....	157177AA	7390
Hose - Upper; Ser. No. 147569 Thru 178174 .....		≠20401 or ●26508
Hose - Upper; Ser. No. 178175 & After .....		●26508
Hose - Lower; Ser. No. 147569 Thru 178174 .....		24228
Hose - Lower; Ser. No. 178175 & After .....		24234
<b>1655</b>		
<b>Oliver 6-Cyl. 265</b>		
<b>1975-1969</b>		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	158679A	7450
Belt - P.S. ....	157176AA	7290
Hose - Upper .....		≠20611 or ●26508
Hose - Lower - Eng. To Pipe .....		24228
Hose - Lower - Pipe To Rad. ....		≠20520
<b>Oliver 6-Cyl. 283 Diesel</b>		
<b>1975-1969</b>		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt.; W/Dual Belts; W/46 1/8" Belt O.C. ....	162071A	②7460
Belt - Fan & Alt.; W/Dual Belts; W/47 1/4" Belt O.C. ....		②▲9470HD
Belt - Fan & Alt.; W/Single Belt .....	157680A	7460
Belt - P.S. ....	157177A	7375
Hose - Upper .....		≠20611 or ●26508
Hose - Lower - Eng. To Pipe .....		24228
Hose - Lower - Pipe To Rad. ....		≠20520
<b>1750</b>		
<b>Oliver 6-Cyl. 283</b>		
<b>1969-1964</b>		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460
Hose - Upper; W/O Row Crop Style .....		●26508
Hose - Upper; W/Row Crop Style .....		●26509
Hose - Lower .....		24234
<b>Oliver 6-Cyl. 310 Diesel</b>		
<b>1969-1964</b>		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460
Hose - Upper; W/O Row Crop Style .....		●26508
Hose - Upper; W/Row Crop Style .....		●26509
Hose - Lower .....		24234
<b>1755</b>		
<b>Oliver 6-Cyl. 283</b>		
<b>1975-1970</b>		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460
Belt - P.S. ....	157176A	7290
Hose - Upper; W/Row Crop Style .....		●26509
Hose - Upper; W/Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>Oliver 6-Cyl. 310 Diesel</b>		
<b>1975-1970</b>		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460

Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>1755 - Continued</b>		
<b>Oliver 6-Cyl. 310 Diesel - Continued</b>		
<b>1975-1970 - Continued</b>		
Belt - P.S.; W/A.C. ....	103926A	7250
Belt - P.S.; W/O A.C. ....	168052A	7417
Hose - Upper; W/Row Crop, Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>1800</b>		
<b>Oliver 6-Cyl. 265</b>		
<b>1963-1960</b>		
Belt - Fan & Gen.; Ser. No. 124395 & Before .....	1M372B	7435
Belt - Fan & Gen.; Ser. No. 124396 & After .....		7440
Belt - P.S. ....	106834A	7320
Hose - Upper .....		≠20611
Hose - Lower; W/O Row Crop Style .....		●26508
Hose - Lower; W/Row Crop Style .....		●26509
<b>Oliver 6-Cyl. 265 LPG</b>		
<b>1962-1960</b>		
Hose - Upper; W/O Row Crop Style; Ser. No. 140076 & Before .....		≠20611
Hose - Upper; W/O Row Crop Style; Ser. No. 140077 & After .....		≠20611 or ●26508
Hose - Upper; W/Row Crop Style .....		≠20611 or ●26509
Hose - Lower; Ser. No. 124395 & Before .....		●26502
Hose - Lower; Ser. No. 124396 & After .....		24236
<b>Oliver 6-Cyl. 283 Diesel</b>		
<b>1963-1960</b>		
Belt - Fan & Gen.; Ser. No. 124395 & Before .....	1M372B	7435
Belt - Fan & Gen.; Ser. No. 124396 & After .....		7440
Belt - P.S.; W/37 5/8" Belt O.C. ....	157177A	7375
Belt - P.S.; W/41 5/8" Belt O.C. ....	1M372A	7417
Hose - Upper .....		●26521
Hose - Lower .....		●26502
<b>1850</b>		
<b>Oliver 6-Cyl. 310</b>		
<b>1969-1964</b>		
Belt - Fan & Alt. ....	157680A	7460
Belt - P.S. ....		7290
Hose - Upper; W/O Row Crop Style .....		●26508
Hose - Upper; W/Row Crop Style .....		●26509
Hose - Lower - Eng. To Pipe .....		24236
Hose - Lower - Pipe To Rad. ....		24236
<b>Oliver 6-Cyl. 384 Diesel</b>		
<b>1969-1964</b>		
Belt - Fan & Alt.; Ser. No. 150421 Thru 168342 .....	158599A	▲9490HD
Belt - Fan & Alt.; Ser. No. 168343 & After ....	162075A	▲9500HD
Belt - P.S. ....	157177AA	7375
Hose - Lower - Eng. To Pipe .....		≠20882
Hose - Lower - Pipe To Rad. ....		24228
<b>Perkins 6-Cyl. 354 Diesel</b>		
<b>1969-1964</b>		
Belt - Fan & Alt.; Ser. No. 150421 Thru 168342 .....	158599A	▲9490HD
Belt - Fan & Alt.; Ser. No. 168343 & After ....	162075A	▲9500HD
Belt - P.S. ....	157177AA	7375
Hose - Lower - Eng. To Pipe .....		≠20882
Hose - Lower - Pipe To Rad. ....		24228
<b>1855</b>		
<b>Oliver 6-Cyl. 310</b>		
<b>1975-1969</b>		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460
Belt - P.S. ....	157176AA	7290
Hose - Upper; W/Row Crop Style .....		●26509
Hose - Upper; W/Wheatland Style .....		●26508

②Two Required ≠Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>1855 - Continued</b>		
<b>Oliver 6-Cyl. 310 - Continued</b>		
<b>1975-1969 - Continued</b>		
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>Oliver 6-Cyl. 310 Diesel</b>		
<b>1975-1969</b>		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460
Belt - P.S.; W/A.C. ....	103926A	7250
Belt - P.S.; W/O A.C. ....	168052A	7417
Hose - Upper; W/Row Crop Style .....		●26509
Hose - Upper; W/Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>1900</b>		
<b>GM 4-Cyl. 212 Diesel</b>		
<b>1963-1960</b>		
Belt - Fan; Ser. No. 124396 & After .....	155985A	▲9400HD
Belt - Fan; Ser. No. 90525 Thru 124395 .....	106093A	▲9390HD
Belt - Gen. ....	1M372A	7417
Belt - P.S.; Ser. No. 90525 Thru 134683 .....	106841A	7280
Hose - Upper .....		●25476
Hose - Lower .....		●26504
<b>1950</b>		
<b>GM 4-Cyl. 212 Diesel</b>		
<b>1970-1964</b>		
Belt - Alt. ....	157751A	7417
Belt - Fan .....	155985A	▲9400HD
Belt - P.S.; Ser. No. 150421 & After; W/32 1/8" Belt O.C. ....	157187AA	7320
Belt - P.S.; Ser. No. 150421 & After; W/34 1/4" Belt O.C. ....	167910A	②7340
Hose - Upper; Ser. No. 150421 Thru 163701 .....		③<21794
		or ●25476
Hose - Upper; Ser. No. 163702 & After .....		③<20046
		or ●25478
Hose - Lower .....		●26504
<b>1950T</b>		
<b>Oliver 6-Cyl. 310 Diesel</b>		
<b>1969</b>		
Belt - A.C. ....	167890A	▲9530HD
Belt - Fan & Alt. ....		②7460
Hose - Upper; W/Row Crop Style .....		③<20611
		or ●26509
Hose - Upper; W/Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>1968</b>		
Belt - A.C.; Ser. No. 204000 & Before .....	167897A	7480
Belt - A.C.; Ser. No. 204001 & After .....	167890A	▲9530HD
Belt - Fan & Alt. ....		②7460
Hose - Upper; W/Row Crop Style .....		③<20611
		or ●26509
Hose - Upper; W/Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>1967</b>		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....		②7460
Hose - Upper; W/Row Crop Style .....		③<20611
		or ●26509
Hose - Upper; W/Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>1955</b>		
<b>Oliver 6-Cyl. 310 Diesel</b>		
<b>1974-1969</b>		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	157680A	②7460
Belt - P.S.; W/A.C. ....	103926A	7250

Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>1955 - Continued</b>		
<b>Oliver 6-Cyl. 310 Diesel - Continued</b>		
<b>1974-1969 - Continued</b>		
Belt - P.S.; W/O A.C. ....	168052A	7417
Hose - Upper; W/Row Crop Style .....		●26509
Hose - Upper; W/Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>2050</b>		
<b>White-Hercules 6-Cyl. 478 Diesel</b>		
<b>1969-1968</b>		
Belt - A.C. ....	167890A	▲9530HD
Belt - Fan .....	166301A	②▲9580HD
Hose - Upper .....		③<20611
		or ●26508
Hose - Lower .....		24240
<b>2150</b>		
<b>White-Hercules 6-Cyl. 478 Diesel</b>		
<b>1969-1968</b>		
Belt - A.C. ....	167890A	▲9530HD
Belt - Fan .....	167836A	②▲9570HD
Hose - Upper .....		③<20611
		or ●26508
Hose - Lower .....		24240
<b>2155</b>		
<b>Minneapolis-Moline 6-Cyl. 504 LPG</b>		
<b>1971</b>		
Hose - Upper .....		●26505
Hose - Lower .....		24238
Hose - By Pass .....		24232
<b>Minneapolis-Moline 6-Cyl. 585 Diesel</b>		
<b>1971</b>		
Belt - Fan & Alt. ....	10A30623	②▲9580HD
Belt - P.S. ....	10A30590	▲9505HD
Hose - Lower .....		24238
Hose - By Pass .....		24232
<b>2255</b>		
<b>Caterpillar 3150 Diesel</b>		
<b>1976-1972</b>		
Belt - A.C. ....	303076253	▲9640HD
Belt - Fan & Alt. ....	303075087	②▲9490HD
Belt - P.S. ....		7300
Hose - Upper - Eng. To Pipe .....		24232
Hose - Upper - Pipe To Rad. ....		24232
Hose - Lower .....		③<20611
		or ●26516
<b>Caterpillar 3208 Diesel</b>		
<b>1976-1972</b>		
Belt - A.C. ....	303076253	▲9640HD
Belt - Fan & Alt. ....	303075087	②▲9490HD
Belt - P.S. ....		7300
Hose - Upper - Eng. To Pipe .....		24236
Hose - Upper - Pipe To Rad. ....		24236
Hose - Lower .....		③<20611
		or ●26509
<b>2655</b>		
<b>Minneapolis-Moline 6-Cyl. 504 LPG</b>		
<b>1972-1970</b>		
Belt - Fan & Alt. ....	200007935	②▲9580HD
Belt - P.S.; Ser. No. 45700132, 45600262 & Before .....	207000472	③7430
Hose - Upper .....		●26505
Hose - Lower .....		24238
Hose - By Pass .....		24232
<b>Minneapolis-Moline 6-Cyl. 585 Diesel</b>		
<b>1972-1970</b>		
Belt - Fan & Alt. ....	200007935	②▲9580HD

②Two Required ③Three Required ③<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>2655 - Continued</b>		
<b>Minneapolis-Moline 6-Cyl. 585 Diesel - Continued</b>		
1972-1970 - Continued		
Belt - P.S.; Ser. No. 45700132, 45600262 & Before .....	207000472	③7430
<b>AG6</b>		
<b>Continental 4-Cyl. 226</b>		
1957-1944		
Belt - Fan .....	141106	TR30428
Belt - Fan & Gen. ....	141199	TR32491
<b>BD</b>		
<b>Hercules 6-Cyl. 298 Diesel</b>		
1956-1946		
Belt - Fan .....	28056	TR28406
Belt - Starter .....	55476	②TR28545
<b>BG</b>		
<b>Hercules 4-Cyl. 320</b>		
1944-1939		
Belt - Fan .....	28056	TR28406
Belt - Starter .....	55476	②TR28545
<b>BGS</b>		
<b>Hercules 4-Cyl. 320</b>		
1955-1946		
Belt - Fan .....	28056	TR28406
Belt - Starter .....	55476	②TR28545
<b>GG</b>		
<b>Hercules 4-Cyl. 133</b>		
1942-1939		
Belt - Fan .....	112019	TR26341
<b>HG</b>		
<b>Hercules 4-Cyl. 133</b>		
1951-1946		
Belt - Fan .....	117423	TR26366
Belt - Fan & Gen. ....	117424	TR28406
<b>Hercules 4-Cyl. 133 Diesel</b>		
1951-1946		
Belt - Fan .....	117423	TR26366
Belt - Fan & Gen. ....	117424	TR28406
<b>OC9</b>		
<b>Hercules DD198</b>		
1965-1959		
Belt - Fan & Gen. ....	606670F	▲9530HD
Hose - Upper .....		②20416
		or ●25482
Hose - Lower .....		●25478
<b>OC12</b>		
<b>Hercules DJXC</b>		
1961-1954		
Belt - Fan & Gen. ....	24270	TR28557
<b>OC15</b>		
<b>Hercules DRXC</b>		
1961-1956		
Belt - Fan .....		TR34506
<b>Super 55</b>		
<b>Oliver 4-Cyl. 144</b>		
1958-1954		
Belt - Fan & Gen.; W/O W.P. ....	1M372A	7417
Belt - Fan & Gen.; W/W.P. ....	1M372B	7435
Hose - Upper .....		②20065
		or ●25473
Hose - Lower .....		●25476
Hose - By Pass .....		24224

Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>Super 55 - Continued</b>		
<b>Oliver 4-Cyl. 144 Diesel</b>		
1958-1954		
Belt - Fan & Gen.; W/O W.P. ....	1M372A	7417
Belt - Fan & Gen.; W/W.P. ....	1M372B	7435
Hose - Upper .....		②20065
		or ●25473
Hose - Lower .....		●25476
Hose - By Pass .....		24224
<b>Super 66</b>		
<b>Oliver 4-Cyl. 144</b>		
1958-1954		
Belt - Fan & Gen.; W/O W.P. ....	1M372A	7417
Belt - Fan & Gen.; W/W.P. ....	1M372B	7435
Hose - Upper .....		②20267
		or ●25472
Hose - Lower .....		24224
<b>Oliver 4-Cyl. 144 Diesel</b>		
1958-1954		
Belt - Fan & Gen.; W/O W.P. ....	1M372A	7417
Belt - Fan & Gen.; W/W.P. ....	1M372B	7435
Hose - Upper .....		②20267
		or ●25472
Hose - Lower .....		24224
<b>Super 77</b>		
<b>Oliver 6-Cyl. 216</b>		
1958-1954		
Belt - Fan .....	C372A	TR28454
Belt - Fan & Gen.; W/O P.S. ....	1M372A	7417
Belt - Fan & Gen.; W/P.S. ....	1M372B	7435
Belt - Gen. ....	A1257A	TR22299
Hose - Upper .....		②20267
		or ●25472
Hose - Lower .....		24224
<b>Oliver 6-Cyl. 216 Diesel</b>		
1958-1954		
Belt - Fan .....	C372A	TR28454
Belt - Fan & Gen.; W/O P.S. ....	1M372A	7417
Belt - Fan & Gen.; W/P.S. ....	1M372B	7435
Belt - Gen. ....	A1257A	TR22299
Hose - Upper .....		②20267
		or ●25472
Hose - Lower .....		24224
<b>Oliver 6-Cyl. 216 LPG</b>		
1958-1954		
Belt - Fan .....	C372A	TR28454
Belt - Fan & Gen.; W/O P.S. ....	1M372A	7417
Belt - Fan & Gen.; W/P.S. ....	1M372B	7435
Belt - Gen. ....	A1257A	TR22299
Hose - Upper .....		②20267
		or ●25472
Hose - Lower .....		24224
<b>Super 88</b>		
<b>Oliver 6-Cyl. 265</b>		
1958-1954		
Belt - Fan & Gen.; W/O P.S. ....	1K372A	7425
Belt - Fan & Gen.; W/P.S. ....	1K372B	7455
Hose - Upper; Molded Hose .....		●25472
Hose - Upper; Strt. Hose .....		24224
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>Oliver 6-Cyl. 265 Diesel</b>		
1958-1954		
Belt - Fan & Gen.; W/O P.S. ....	1K372A	7425
Belt - Fan & Gen.; W/P.S. ....	1K372B	7455
<b>Oliver 6-Cyl. 265 LPG</b>		
1958-1954		
Belt - Fan & Gen.; W/O P.S. ....	1K372A	7425
Belt - Fan & Gen.; W/P.S. ....	1K372B	7455

②Two Required ③Three Required ④Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>OLIVER - Continued</b>		
<b>Super 88 – Continued</b>		
<b>Oliver 6–Cyl. 265 LPG – Continued</b>		
1958–1954 – Continued		
Hose - Upper; Molded Hose .....		●25472
Hose - Upper; Strt. Hose .....		24224
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		24224
<b>Super 99</b>		
<b>GM 3–Cyl. 213 Diesel</b>		
1958–1954		
Belt - Fan .....	5189569	TR34467
<b>Oliver 6–Cyl. 302</b>		
1958–1954		
Belt - Fan & Gen. ....	7A372B	♣9440HD
<b>Oliver 6–Cyl. 302 Diesel</b>		
1958–1954		
Belt - Fan & Gen. ....	7A372B	♣9440HD
<b>SAME</b>		
<b>Corsaro 70</b>		
<b>SAME 4–Cyl. 221 Diesel</b>		
1986–1980		
Belt - Blower & Alt. ....		②7560
<b>Delfino 35</b>		
<b>SAME 2–Cyl. 110 Diesel</b>		
1985–1981		
Belt - Blower & Alt. ....		7541
<b>Explorer 75</b>		
<b>SAME 4–Cyl. 244 Diesel</b>		
1987–1985		
Belt - Blower & Alt. ....		②7520
<b>Explorer 90</b>		
<b>SAME 4–Cyl. 244 Diesel</b>		
2001–1987		
Belt - Blower & Alt. ....		7525
<b>Frutteto II 60</b>		
<b>SAME 3–Cyl. 183 Diesel</b>		
2001–1992		
Belt - Alt. ....		7280
<b>Frutteto II 75</b>		
<b>SAME 4–Cyl. 244 Diesel</b>		
2001–1992		
Belt - Alt. ....		7280
<b>Frutteto II 85</b>		
<b>SAME 4–Cyl. 244 Diesel</b>		
2001–1990		
Belt - Alt. ....		7280
<b>Mercury 75</b>		
<b>SAME 4–Cyl. 254 Diesel</b>		
1986–1982		
Belt - Blower & Alt. ....		②7570
<b>Mercury 85</b>		
<b>SAME 4–Cyl. 254 Diesel</b>		
1991–1982		
Belt - Blower & Alt. ....		②7570

Application	OEM No.	Our No.
<b>SAME - Continued</b>		
<b>Minitaurus 60</b>		
<b>SAME 3–Cyl. 190 Diesel</b>		
1988–1980		
Belt - Blower & Alt. ....		②7560
<b>Row Crop 85</b>		
<b>SAME 4–Cyl. 254 Diesel</b>		
1996–1984		
Belt - Blower & Alt. ....		②7570
<b>Vigneron 60</b>		
<b>SAME 3–Cyl. 190 Diesel</b>		
1986–1984		
Belt - Blower & Alt. ....		②7560
<b>SHEPPARD</b>		
<b>SD2</b>		
<b>Sheppard 2–Cyl. 142 Diesel</b>		
1957–1949		
Belt - Fan & Gen. ....	0400251	TR22570
<b>SD3</b>		
<b>Sheppard 3–Cyl. 188 Diesel</b>		
1957–1948		
Belt - Fan & Gen. ....	0400251	TR22570
<b>SD4</b>		
<b>Sheppard 4–Cyl. 318 Diesel</b>		
1957–1955		
Belt - Fan & Gen. ....	0400050	7575
<b>SDG2</b>		
<b>Sheppard 2–Cyl. 142 Diesel</b>		
1956–1950		
Belt - Fan & Gen. ....	0400251	TR22570
<b>SDG3</b>		
<b>Sheppard 3–Cyl. 213 Diesel</b>		
1956–1950		
Belt - Fan & Gen. ....	0400251	TR22570
<b>SDO2</b>		
<b>Sheppard 2–Cyl. 142 Diesel</b>		
1956–1950		
Belt - Fan & Gen. ....	0400251	TR22570
<b>SDO3</b>		
<b>Sheppard 3–Cyl. 188 Diesel</b>		
1956–1950		
Belt - Fan & Gen. ....	0400251	TR22570
<b>STEIGER</b>		
<b>Bearcat 1000</b>		
<b>Cummins L10 Diesel</b>		
1987–1986		
Belt - A.C. ....	016864	♣9390HD
Belt - Fan ....	3034942	♣K080465HD
Hose - Upper .....		●26525
<b>Bearcat I</b>		
<b>Caterpillar 3208 Diesel</b>		
1974–1970		
Belt - A.C. ....	061451	♣9510HD
Belt - Fan .....	06019	②♣9550HD
Belt - W.P. & Alt.; W/55A. Alt. ....	06019	②♣9550HD
Belt - W.P. & Alt.; W/72A. Alt. ....	061464	②♣9520HD

②Two Required ●Flexible Coolant Hose ♣Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>STEIGER - Continued</b>		
<b>Bearcat II</b>		
<b>Caterpillar 3208 Diesel</b>		
1975-1974		
Belt - A.C. ....	061451	▲9510HD
Belt - Fan ....	06019	②▲9550HD
Belt - W.P. & Alt.; W/55A. Alt. ....	06019	②▲9550HD
Belt - W.P. & Alt.; W/72A. Alt. ....	061464	②▲9520HD
<b>Bearcat II ST225</b>		
<b>Caterpillar 3306 Diesel</b>		
1976-1974		
Belt - Fan & Alt. ....		③▲9630HD
Belt - Fan To A.C. ....		▲9463HD
<b>Bearcat III PT225</b>		
<b>Caterpillar 3306 Diesel</b>		
1983-1977		
Belt - Fan ....	901502T1	③▲9690HD
Belt - Fan & Alt. ....	06135	③▲9630HD
Belt - Fan To A.C. ....	061428	▲9463HD
<b>Cougar 1000</b>		
<b>Cummins L10 Diesel</b>		
1989-1986		
Belt - A.C. ....	016864	▲9390HD
Belt - Fan ....	3034942	▲K080465HD
Belt - W.P. & Alt. ....		▲K050336HD
Hose - Lower ....		≧<21115
<b>Cougar CR1225</b>		
<b>Caterpillar 6-Cyl. 638 Diesel</b>		
1985		
Belt - A.C. ....		▲9463HD
Belt - Fan & Alt. ....		③▲9570HD
<b>Cougar II</b>		
<b>Caterpillar 3306 Diesel</b>		
1976-1974		
Belt - Fan & Alt. ....	061463A	③▲9650HD
Belt - Fan To A.C. ....		▲9463HD
Hose - Upper ....		●26533
<b>Cougar II ST300</b>		
<b>Caterpillar 6-Cyl. 638 Diesel</b>		
1976-1974		
Belt - Fan ....		▲9570HD
Belt - Fan, Alt. & A.C. ....		▲9610HD
Belt - Hyd. Pump ....		▲9370HD
Hose - Upper ....		●26532
<b>Cougar III PT270</b>		
<b>Caterpillar 3306 Diesel</b>		
1981-1977		
Belt - A.C. ....		▲9455HD
Belt - Fan & Alt. ....	06135	③▲9630HD
Hose - Upper - Eng. To Pipe ....		24440
Hose - Upper - Pipe To Rad. ....		24440
Hose - Lower - Eng. To Pipe ....		24440
Hose - Lower - Pipe To Rad. ....		24440
<b>Cougar III PTA251</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1981-1980		
Belt - A.C. ....	178509	TR28445
Belt - Alt. ....	178440	②▲9463HD
Belt - W.P. ....		▲K060435HD
<b>Cougar III PTA270</b>		
<b>Caterpillar 3306 Diesel</b>		
1981-1980		
Belt - A.C. ....	019344	▲9490HD
Belt - Fan & Alt. ....	06096	③▲9625HD
Hose - Upper - Eng. To Pipe ....		24440

Application	OEM No.	Our No.
<b>STEIGER - Continued</b>		
<b>Cougar III PTA270 - Continued</b>		
<b>Caterpillar 3306 Diesel - Continued</b>		
1981-1980 - Continued		
Hose - Upper - Pipe To Rad. ....		24440
Hose - Lower - Cooler To Rad. ....		≧<21042
<b>Cougar III PTA280</b>		
<b>Cummins NTC290 Diesel</b>		
1983-1981		
Belt - A.C. ....		TR22386
Belt - Alt. ....		②▲9480HD
Belt - Fan ....	178624	②TR28473
Belt - W.P. ....	215356	②6596
<b>Cougar III ST251</b>		
<b>Cummins NTC290 Diesel</b>		
1982-1976		
Belt - A.C. ....		TR22386
Belt - Alt. ....		②▲9480HD
Belt - Fan ....	178624	②TR28473
Belt - W.P. ....	215356	②6596
<b>Cougar III ST270</b>		
<b>Caterpillar 3306 Diesel</b>		
1981-1976		
Belt - A.C. ....	061428	▲9463HD
Belt - Fan & Alt. ....	06135	▲9630HD
Hose - Lower ....		≧<21115
<b>Cougar IV CM280</b>		
<b>Caterpillar 3406 Diesel</b>		
1985-1983		
Belt - Alt. ....		BX71
Belt - Fan ....		②TR22648
<b>Cougar IV KS280</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1985-1983		
Belt - A.C. ....		▲9395HD
Belt - Alt. ....	178440	②▲9463HD
Belt - Fan ....		②TR28454
Belt - W.P. ....	217638	▲K060435HD
<b>Lion 1000</b>		
<b>Caterpillar 3406 Diesel</b>		
1989-1986		
Belt - Fan ....		TR22588
<b>Cummins 6-Cyl. 855 Diesel</b>		
1989-1986		
Belt - Alt. ....		▲9600HD
Belt - Fan ....		▲K080400HD
Belt - W.P. ....		▲K060435HD
<b>Panther CP1400</b>		
<b>Caterpillar 6-Cyl. 893 Diesel</b>		
1987-1982		
Belt - A.C. ....		▲9447HD
Belt - Fan ....		②TR22588
<b>Panther II ST310</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1976-1974		
Belt - A.C. ....	061473	TR22386
Belt - Alt. ....		②▲9463HD
Belt - Fan ....	178697	②TR28454
Belt - W.P. ....	215356	②6596
Hose - Upper ....		24436
Hose - Lower ....		●26533

②Two Required ③Three Required ≧<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>STEIGER - Continued</b>		
<b>Panther III PT350</b>		
<b>Cummins V-8 903 Diesel</b>		
1981-1977		
Belt - A.C. ....	178618	TR22380
Belt - Alt. ....	178472	②▲9390HD
Belt - Fan & W.P. ....		③▲9710HD
Hose - Upper - Eng. To Pipe .....		24428
Hose - Upper - Pipe To Rad. ....		24428
Hose - Lower - Cooler To Rad. ....		③<21042
<b>Panther III PTA325</b>		
<b>Caterpillar 6-Cyl. 893 Diesel</b>		
1983-1979		
Hose - Upper .....		●26537
<b>Panther III ST310</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1983-1976		
Belt - A.C. ....		▲9390HD
Belt - Fan .....	178566	②TR28473
Belt - W.P. & Idler; W/O Aux. Rad. ....	215356	②6596
Hose - Upper .....		24436
<b>Panther III ST320</b>		
<b>Cummins V-8 903 Diesel</b>		
1977-1976		
Belt - A.C. ....	178618	TR22380
Belt - Alt. ....	178472	②▲9390HD
Belt - Fan & W.P. ....		③▲9710HD
Hose - Upper - Eng. To Pipe .....		24428
Hose - Upper - Pipe To Rad. ....		24428
Hose - Lower - Cooler To Rad. ....		③<21042
<b>Panther IV SM325</b>		
<b>Komatsu 6-Cyl. 674 Diesel</b>		
1985-1983		
Belt - A.C. ....		▲9550HD
Belt - Fan & Alt. ....		②TR28706
<b>Panther KP1360</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1985-1982		
Belt - A.C. ....	178472	▲9390HD
Belt - Alt. ....	178440	②▲9463HD
Belt - Fan .....	178509	②TR28445
Belt - W.P. ....	217638	▲K060435HD
<b>Panther KP1400</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1985-1982		
Belt - A.C. ....	178472	▲9390HD
Belt - Alt. ....		②▲9463HD
Belt - Fan .....		②TR24449
Belt - W.P. ....	217638	▲K060435HD
Hose - Upper .....		●26524
<b>Puma 1000</b>		
<b>Steiger 6-Cyl. 505 Diesel</b>		
1988-1986		
Belt - A.C. ....	061451A	▲9520HD
Belt - Fan & Alt. ....	3905866	▲K080600HD
Hose - Upper .....		③<21418
		or ●26524
Hose - Lower - Eng. To Pipe .....		③<21473
<b>Tiger III ST450</b>		
<b>Caterpillar 3408 Diesel</b>		
1983-1978		
Belt - A.C. ....		TR22625
Belt - Alt. ....	206996	K050370
Hose - Upper - Eng. To Pipe .....		24440
Hose - Upper - Pipe To Rad. ....		24440
Hose - Lower - Eng. To Pipe .....		24456
Hose - Lower - Pipe To Rad. ....		24456

Application	OEM No.	Our No.
<b>STEIGER - Continued</b>		
<b>Wildcat I</b>		
<b>Caterpillar 3145 Diesel</b>		
1973-1969		
Belt - A.C. ....		▲9610HD
Belt - Alt. ....	06019	▲9550HD
Belt - Fan .....		▲9465HD
<b>Wildcat I Super</b>		
<b>Caterpillar 3150 Diesel</b>		
1974-1969		
Belt - A.C. ....	061428	▲9463HD
Belt - Alt.; W/55A. Alt. ....	06019	②▲9550HD
Belt - Alt.; W/72A. Alt. ....	061464	②▲9520HD
Belt - Fan .....	06019	②▲9550HD
<b>Wildcat III RC210</b>		
<b>Caterpillar 3208 Diesel</b>		
1977-1976		
Belt - A.C. ....	061451	▲9510HD
Belt - Alt. ....	061464	②▲9525HD
Belt - Fan & Idler .....	061416	③▲9700HD
<b>Wildcat III ST210</b>		
<b>Caterpillar 3208 Diesel</b>		
1980-1976		
Belt - A.C. ....	061451	▲9510HD
Belt - Alt. ....	061464	②▲9525HD
Belt - Fan & Idler .....	061416	③▲9700HD
<b>TYM AMERICA</b>		
<b>T233</b>		
<b>Mitsubishi 3-Cyl. 69 Diesel</b>		
2014-2006		
Belt - Fan .....	MD025523	7375
<b>T273</b>		
<b>Mitsubishi 3-Cyl. 80 Diesel</b>		
2013-2006		
Belt - Fan .....	MD025523	7375
<b>T353</b>		
<b>Mitsubishi 4-Cyl. 107 Diesel</b>		
2014-2010		
Belt - Fan .....	MD041704	7380
<b>UNIVERSAL TRACTOR CANADA LTD</b>		
<b>U640</b>		
<b>Universal 4-Cyl. 219 Diesel</b>		
1999-1984		
Belt - Fan & Alt. ....		7450
Hose - Lower .....		②24222
<b>U1010</b>		
<b>Universal 6-Cyl. 329 Diesel</b>		
1998-1984		
Belt - Fan .....		②▲9420HD
Belt - W.P. & Alt. ....		7435
Hose - Lower - Eng. To Pipe .....		24224
Hose - Lower - Pipe To Rad. ....		●25472

②Two Required ③Three Required ③<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Agricultural Equipment



Application	OEM No.	Our No.
<b>VALTRA-VALMET</b>		
<b>78 Viking; 880</b>		
<b>MWM 4-Cyl. 239 Diesel</b>		
1995		
Belt - Fan & Alt. ....		▲9485HD
<b>980</b>		
<b>MWM 4-Cyl. 239 Diesel</b>		
1990-1988		
Belt - Fan & Alt. ....		▲9485HD
<b>VERSATILE</b>		
<b>145</b>		
<b>Cummins V-8 470 Diesel</b>		
1971-1967		
Belt - Hyd. Pump - Left Side .....		TR22517
Belt - Hyd. Pump - Right Side .....		TR22514
Belt - W.P. & Alt.; W/55A. Alt. ....		②▲9500HD
<b>150</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1981-1977		
Belt - Fan & Alt.; W/54 1/4" Belt O.C. ....		▲9530HD
Belt - Fan & Alt.; W/54 1/4" Belt O.C. ....	34922	▲9540HD
Belt - Hyd. Pump .....	47613	TR22443
Hose - Upper .....		●25480
Hose - Lower .....		●25478
<b>256</b>		
<b>Cummins 4-Cyl. 239 Diesel</b>		
1988-1984		
Belt - A.C. ....	86452	▲9415HD
Belt - Fan & Alt. ....	3903091	▲K080560HD
<b>276</b>		
<b>Cummins 4-Cyl. 239 Diesel</b>		
1991-1985		
Belt - Fan & Alt. ....	3903091	▲K080560HD
<b>276 II</b>		
<b>Ford 4-Cyl. 268 Diesel</b>		
1991-1985		
Belt - A.C. ....		▲9425HD
Belt - Fan & Alt. ....		②▲9570HD
Hose - Upper .....		●26506
<b>400</b>		
<b>Ford 6-Cyl. 200</b>		
1984-1969		
Belt - Fan & Alt. ....	C5DE 8620 C	7340
Belt - Gov. ....	C7ZZ 8620 F	7312
Hose - Upper .....		●25305
Hose - Lower .....		●25484
<b>500</b>		
<b>Cummins V-8 504 Diesel</b>		
1979-1977		
Belt - W.P. ....	196937	②TR22534
<b>555</b>		
<b>Cummins V-8 555 Diesel</b>		
1987-1979		
Belt - Alt. ....		②7495
Belt - Fan & W.P. ....	178598	②TR22495
Hose - Upper .....		●26512
<b>700</b>		
<b>Cummins V-8 555 Diesel</b>		
1977-1971		
Belt - A.C. ....	20974	②▲9425HD
Belt - Alt. ....	178434	②7365
Belt - Fan & W.P. ....	201927	②▲9540HD
Hose - Upper .....		●26513

Application	OEM No.	Our No.
<b>VERSATILE - Continued</b>		
<b>700 - Continued</b>		
<b>Cummins V-8 555 Diesel - Continued</b>		
1977-1971 - Continued		
Hose - Lower .....		②<20756
<b>750</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1977-1976		
Belt - A.C. ....	22925	TR22448
Belt - Alt. ....	200549	②▲9465HD
Belt - Fan .....	178682	②TR28429
Belt - W.P. ....	215356	②6596
<b>800</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1977-1973		
Belt - A.C. ....	22925	TR22448
Belt - Alt. ....	200549	②▲9465HD
Belt - Fan .....	178682	②TR28429
Belt - W.P. ....	215356	②6596
Hose - Upper .....		●26524
Hose - Lower - Eng. To Pipe .....		24240
Hose - Lower - Pipe To Rad. ....		24244
<b>835</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1987-1978		
Belt - A.C. ....	178678	TR22448
Belt - Alt. ....		②▲9463HD
Belt - Fan .....	178682	②TR28429
Belt - W.P. ....		▲K060435HD
<b>846</b>		
<b>Cummins 6-Cyl. 611 Diesel</b>		
1992-1987		
Belt - A.C. ....	00092756	▲9385HD
Belt - Alt. ....	3037425	▲K050340HD
Belt - Fan .....	3034944	▲K080545HD
Hose - Upper .....		②24436
Hose - Lower .....		②24440
<b>850</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1977-1973		
Belt - A.C. ....	22925	TR22448
Belt - Alt. ....	200549	②▲9465HD
Belt - Fan .....	178682	②TR28429
Belt - W.P. ....	215356	②6596
Hose - Upper .....		●26524
Hose - Lower - Eng. To Pipe .....		24240
Hose - Lower - Pipe To Rad. ....		24244
<b>875</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1987-1978		
Belt - A.C. ....	22925	TR22448
Belt - Alt. ....		②▲9470HD
Belt - Fan .....	178682	②TR28429
Belt - W.P. ....	215356	②6596
Hose - Lower .....		24240
<b>876</b>		
<b>Cummins 6-Cyl. 611 Diesel</b>		
1993-1985		
Belt - A.C. ....	00092756	▲9385HD
Belt - Alt. ....	3037425	▲K050340HD
Belt - Fan .....	3034944	▲K080545HD
Hose - Upper .....		②24436
Hose - Lower .....		②24440
<b>895</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1987-1980		
Belt - A.C. ....	178678	TR22448

②Two Required <Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>VERSATILE - Continued</b>		
<b>895 - Continued</b>		
<b>Cummins 6-Cyl. 855 Diesel - Continued</b>		
1987-1980 - Continued		
Belt - Alt. ....	178440	▲9463HD
Belt - W.P. ....	217638	▲K060435HD
<b>900</b>		
<b>Cummins V-8 903 Diesel</b>		
1975-1972		
Belt - A.C.; W/Dual Belts .....	20974	②▲9425HD
Belt - A.C.; W/Single Belt .....	178598	TR22495
Belt - Alt.; W/42 1/2" Belt O.C. ....		②▲9425HD
Belt - Fan & W.P. ....	202046	③▲9580HD
Belt - Hyd. Pump .....		TR22514
Hose - Upper - Left Side .....		●26524
Hose - Upper - Right Side .....		●26524
Hose - Lower .....		24444
<b>900-2</b>		
<b>Cummins V-8 903 Diesel</b>		
1978-1976		
Belt - A.C.; W/Dual Belts .....	20974	②▲9425HD
Belt - A.C.; W/Single Belt .....	178598	TR22495
Belt - Alt.; W/42 1/2" Belt O.C. ....		②▲9425HD
Belt - Fan & W.P. ....	202046	③▲9580HD
Belt - Hyd. Pump .....		TR22514
Hose - Upper - Left Side .....		②●26524
Hose - Lower .....		24244
<b>935</b>		
<b>Cummins V-8 903 Diesel</b>		
1982-1978		
Belt - A.C. ....	178598	TR22495
Belt - Fan & W.P. ....	202047	③▲9585HD
Hose - Upper - Left Side .....		●26524
Hose - Upper - Right Side .....		●26524
<b>936</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1991-1985		
Belt - A.C. ....	178428	▲9425HD
Belt - Alt. ....	178440	②▲9463HD
Belt - Fan .....	178707	②TR28437
Belt - W.P. ....	217638	▲K060435HD
Hose - Upper; W/2 1/4" I.D. Hose .....		24936
Hose - Upper; W/2" I.D. Hose .....		24932
Hose - Lower; W/2 1/2" I.D. Hose .....		②24440
Hose - Lower; W/2 1/4" I.D. Hose .....		②24436
<b>950</b>		
<b>Cummins V-8 903 Diesel</b>		
1982-1977		
Belt - A.C. ....		TR22495
Belt - Alt. ....	178608	②TR28510
Belt - Fan & W.P. ....		③▲9590HD
Hose - Upper - Left Side .....		●26524
Hose - Upper - Right Side .....		●26524
<b>976</b>		
<b>Cummins 6-Cyl. 855 Diesel</b>		
1993-1985		
Belt - A.C. ....		②▲9430HD
Belt - Alt. ....		▲9463HD
Belt - Fan .....	178707	②TR28437
Belt - W.P. ....	217638	▲K060435HD
Hose - Upper .....		●26524
Hose - Lower - Eng. To Pipe .....		24440
Hose - Lower - Pipe To Rad. ....		24440
<b>1150</b>		
<b>Cummins 6-Cyl. 1150 Diesel</b>		
1985-1981		
Belt - A.C. ....	00063727	▲9470HD
Belt - W.P. To Alt. ....	205913	▲K050360HD
Hose - Upper .....		②●26524

Application	OEM No.	Our No.
<b>VERSATILE - Continued</b>		
<b>1150 - Continued</b>		
<b>Cummins 6-Cyl. 1150 Diesel - Continued</b>		
1985-1981 - Continued		
Hose - Lower .....		②24256
<b>1156</b>		
<b>Cummins 6-Cyl. 1150 Diesel</b>		
1992-1986		
Belt - A.C. ....	00063727	▲9470HD
Belt - W.P. To Alt. ....	205913	▲K050360HD
Hose - Upper .....		②●26524
Hose - Lower .....		②24256
<b>WHITE</b>		
<b>2-30</b>		
<b>Isuzu 3-Cyl. 91 Diesel</b>		
1984-1979		
Belt - Fan & Alt. ....	5136710400	▲9400HD
<b>2-35</b>		
<b>Isuzu 3-Cyl. 108 Diesel</b>		
1984-1979		
Belt - Fan & Alt. ....		▲9412HD
<b>2-44 Industrial</b>		
<b>White 4-Cyl. 155</b>		
1975-1968		
Belt - Fan & Gen. ....		7450
Belt - Hyd. Pump .....		7430
Hose - Upper .....		≈<20433
		or ●25473
<b>White 4-Cyl. 155 Diesel</b>		
1975-1968		
Belt - Fan & Gen. ....		7450
Belt - Hyd. Pump .....		7430
Hose - Upper .....		≈<20433
		or ●25473
<b>2-50</b>		
<b>Fiat 3-Cyl. 158 Diesel</b>		
1980-1976		
Belt - Fan & Alt. ....	4624737	7450
<b>2-55</b>		
<b>Isuzu 4-Cyl. 199 Diesel</b>		
1987-1982		
Belt - Fan & Alt. ....		TR24424
<b>2-60</b>		
<b>Fiat 4-Cyl. 211 Diesel</b>		
1980-1976		
Belt - Fan & Alt. ....	676865A	7450
Hose - Lower - Eng. To Pipe .....		20351
Hose - Lower - Pipe To Rad. ....		20351
<b>2-62</b>		
<b>Isuzu 4-Cyl. 219 Diesel</b>		
1981-1979		
Belt - Fan & Alt. ....		TR22474
<b>2-65</b>		
<b>Isuzu 4-Cyl. 235 Diesel</b>		
1987-1982		
Belt - Fan & Alt. ....		TR22461
<b>2-70</b>		
<b>White 6-Cyl. 265</b>		
1982-1976		
Belt - Fan & Alt. ....	158679A	7450
Hose - Upper .....		≈<20611
		or ●26510

②Two Required ③Three Required ≈<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>WHITE - Continued</b>		
<b>2-70 - Continued</b>		
<b>White 6-Cyl. 265 - Continued</b>		
1982-1976 - Continued		
Hose - Lower - Eng. To Pipe .....		24436
Hose - Lower - Pipe To Rad. ....		24436
<b>White 6-Cyl. 283 Diesel</b>		
1982-1976		
Belt - Fan & Alt. ....	157680A	7460
<b>2-75</b>		
<b>Isuzu 6-Cyl. 329 Diesel</b>		
1987-1982		
Belt - Fan & Alt. ....		TR28473
<b>2-78 Industrial</b>		
<b>White 6-Cyl. 265</b>		
1975-1968		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	158679A	7450
Belt - P.S. ....	157176AA	7290
<b>White 6-Cyl. 283 Diesel</b>		
1975-1968		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460
Belt - P.S. ....	157177AA	7375
<b>2-85</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1982-1975		
Belt - A.C. ....		▲9385HD
Belt - Fan & Alt. ....		②7570
Hose - Upper .....		≧21379
	or	●26509
Hose - Lower - Eng. To Pipe .....		24432
Hose - Lower - Pipe To Rad. ....		24432
<b>2-88</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1987-1982		
Belt - A.C. ....		▲9390HD
Belt - Fan & Alt. ....		②▲9590HD
Hose - Upper .....		≧20611
	or	●26509
<b>2-105</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1982-1974		
Belt - A.C. ....	303143589	▲9375HD
Belt - Fan & Alt. ....		②7570
Hose - Upper .....		≧21379
	or	●26509
Hose - Lower - Eng. To Pipe .....		24432
Hose - Lower - Pipe To Rad. ....		24432
<b>2-110</b>		
<b>Perkins 6-Cyl. 354 Diesel</b>		
1987-1982		
Belt - A.C. ....		▲9390HD
Belt - Fan & Alt. ....	303354288	②▲9590HD
Hose - Upper .....		20206
	or	●26508
<b>2-115 Industrial</b>		
<b>GM 4-Cyl. 212 Diesel</b>		
1975-1968		
Belt - Fan & Alt.; W/40 1/4" Belt O.C. ....		▲9400HD
Belt - Fan & Alt.; W/42 4/8" Belt O.C. ....		7420
Belt - P.S.; W/Dual Belts .....		②7340
Belt - P.S.; W/Single Belt .....		7315

Application	OEM No.	Our No.
<b>WHITE - Continued</b>		
<b>2-135</b>		
<b>White 6-Cyl. 478 Diesel</b>		
1982-1976		
Belt - A.C.; Ser. No. 272663 Thru 272916 ...	303155102	▲9540HD
Belt - A.C.; Ser. No. 272917 & After .....		▲9570HD
Belt - Fan & Alt.; W/58 1/4" Belt O.C. ....	166422A	②▲9580HD
Belt - Fan & Alt.; W/58 3/4" Belt O.C. ....		▲9585HD
Belt - Fan & Alt.; W/59 1/4" Belt O.C. ....	156422A	▲9590HD
Hose - Upper .....		≧21379
Hose - Lower .....		20564
<b>2-150</b>		
<b>White 6-Cyl. 585 Diesel</b>		
1976-1975		
Belt - A.C. ....	303155102	▲9540HD
Belt - Fan & Alt.; W/58 3/4" Belt O.C. ....	200009089	②▲9585HD
Belt - Fan & Alt.; W/59 1/4" Belt O.C. ....		▲9590HD
Hose - Upper .....		●26506
Hose - Lower .....		24240
<b>2-155</b>		
<b>White 6-Cyl. 478 Diesel</b>		
1982-1976		
Belt - A.C.; Ser. No. 272663 Thru 272916 ...	303155102	▲9540HD
Belt - A.C.; Ser. No. 272917 & After .....		▲9570HD
Belt - Fan & Alt.; W/58 1/4" Belt O.C. ....	166422A	②▲9580HD
Belt - Fan & Alt.; W/58 3/4" Belt O.C. ....		▲9585HD
Belt - Fan & Alt.; W/59 1/4" Belt O.C. ....	156422A	▲9590HD
Hose - Upper .....		≧21379
Hose - Lower - Eng. To Pipe .....		24448
Hose - Lower - Pipe To Rad. ....		24440
<b>2-180</b>		
<b>Caterpillar 3208 Diesel</b>		
1982-1977		
Belt - Alt. & A.C. ....		②▲9720HD
Belt - Fan .....		②▲9540HD
Belt - W.P. ....		②▲9490HD
<b>4-78 Industrial</b>		
<b>White 6-Cyl. 265</b>		
1975-1968		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	158679A	7450
Belt - P.S. ....	157176AA	7290
<b>White 6-Cyl. 283 Diesel</b>		
1975-1968		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460
Belt - P.S. ....	157177AA	7375
<b>4-115 Industrial</b>		
<b>GM 4-Cyl. 212 Diesel</b>		
1975-1968		
Belt - Fan & Alt.; W/40 1/4" Belt O.C. ....		▲9400HD
Belt - Fan & Alt.; W/42 4/8" Belt O.C. ....		7420
Belt - P.S.; W/Dual Belts .....		②7340
Belt - P.S.; W/Single Belt .....		7315
<b>4-150</b>		
<b>Caterpillar 3208 Diesel</b>		
1978-1974		
Belt - A.C. ....	303077284	▲9405HD
Belt - Fan & Alt. ....	303075079	②▲9490HD
Hose - Upper .....		≧20356
	or	●26510
Hose - Lower - Eng. To Pipe .....		≧20424
Hose - Lower - Pipe To Rad. ....		23567
<b>4-180</b>		
<b>Caterpillar 3208 Diesel</b>		
1978-1975		
Belt - A.C. ....	303077284	▲9405HD
Belt - Fan & Alt. ....	303075079	②▲9490HD

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>WHITE - Continued</b>		
<b>4-180 - Continued</b>		
<b>Caterpillar 3208 Diesel - Continued</b>		
1978-1975 - Continued		
Hose - Upper .....		②<20356 or ●26510
Hose - Lower - Eng. To Pipe .....		②<20424
Hose - Lower - Pipe To Rad. ....		23567
<b>4-210</b>		
<b>Caterpillar 3208 Diesel</b>		
1982-1978		
Belt - A.C. ....		▲9319HD
Belt - Fan & Alt. ....	303075079	②▲9490HD
<b>4-225</b>		
<b>Caterpillar 3208 Diesel</b>		
1987-1983		
Belt - Fan .....	303302857	②▲9550HD
Belt - W.P. ....	1P4334	②▲9490HD
<b>4-270</b>		
<b>Caterpillar 3306 Diesel</b>		
1988-1983		
Belt - A.C. ....		▲9455HD
Belt - Fan & Alt.; W/72 1/4" Belt O.C. ....		③▲9720HD
Belt - Fan & Alt.; W/73 1/4" Belt O.C. ....		③▲9730HD
<b>60 American</b>		
<b>Cummins 4-Cyl. 239 Diesel</b>		
1991-1989		
Belt - A.C. ....	303315134	▲9400HD
Belt - Fan & Alt. ....	3911559	▲K080620HD
Hose - Upper .....		●26511
Hose - Lower .....		●26519
<b>80 American</b>		
<b>Cummins 4-Cyl. 239 Diesel</b>		
1991-1989		
Belt - A.C. ....	303315134	▲9400HD
Belt - Fan & Alt.; W/61 1/8" Belt O.C. ....	3911563	▲K080605HD
Belt - Fan & Alt.; W/62 1/2" Belt O.C. ....	3911559	▲K080620HD
Hose - Upper .....		●26511
Hose - Lower .....		●26519
<b>100</b>		
<b>Cummins 6-Cyl. 359 Diesel</b>		
1989-1987		
Belt - Fan & Alt. ....	3903099	▲K080620HD
Belt - Fan To A.C. ....		▲9403HD
Hose - Lower .....		24936
<b>120</b>		
<b>Cummins 6-Cyl. 359 Diesel</b>		
1989-1987		
Belt - A.C. ....		▲9405HD
Belt - Fan & Alt. ....	3903098	▲K080605HD
Hose - Lower .....		24936
<b>125 Workhorse</b>		
<b>Cummins 6-Cyl. 359 Diesel</b>		
1992-1990		
Belt - Fan & A.C. ....	303315134	▲9400HD
Belt - Fan, Alt. & Idler .....		▲K080605HD
Hose - Upper .....		●26511
Hose - Lower .....		●26520
<b>140</b>		
<b>Cummins 6-Cyl. 359 Diesel</b>		
1989-1987		
Belt - Fan & Alt. ....	3903099	▲K080620HD
Belt - Fan To A.C. ....		▲9400HD
Hose - Lower .....		24936

Application	OEM No.	Our No.
<b>WHITE - Continued</b>		
<b>145 Workhorse</b>		
<b>Cummins 6-Cyl. 359 Diesel</b>		
1992-1990		
Belt - Fan & Alt. ....	3911559	▲K080620HD
Belt - Fan To A.C. ....	303315134	▲9400HD
<b>160</b>		
<b>Cummins 6-Cyl. 505 Diesel</b>		
1989-1987		
Belt - A.C.; W/40 3/8" Belt O.C. ....	303315134	▲9400HD
Belt - Fan & Alt.; W/66 5/8" Belt O.C. ....	3911578	▲K080660HD
Belt - Fan & Alt.; W/67 5/8" Belt O.C. ....	3911567	▲K080670HD
Belt - Fan & Alt.; W/68 1/8" Belt O.C. ....	3911579	▲K080675HD
Belt - Fan & Alt.; W/69 1/4" Belt O.C. ....	3911580	▲K080685HD
Hose - Upper .....		②<20731
Hose - Lower - Eng. To Pipe .....		②<21473
Hose - Lower - Pipe To Rad. ....		●26507
<b>170 Workhorse</b>		
<b>Cummins 6-Cyl. 505 Diesel</b>		
1992-1990		
Belt - A.C.; W/40 3/8" Belt O.C. ....	303315134	▲9400HD
Belt - Fan & Alt.; W/66 5/8" Belt O.C. ....	3911578	▲K080660HD
Belt - Fan & Alt.; W/67 5/8" Belt O.C. ....	3911567	▲K080670HD
Belt - Fan & Alt.; W/68 1/8" Belt O.C. ....	3911579	▲K080675HD
Hose - Upper .....		②<20731
Hose - Lower - Eng. To Pipe .....		21901
Hose - Lower - Pipe To Rad. ....		●26507
<b>185</b>		
<b>Cummins 6-Cyl. 505 Diesel</b>		
1989-1987		
Belt - A.C.; W/40 3/8" Belt O.C. ....	303315134	▲9400HD
Belt - Fan & Alt.; W/66 5/8" Belt O.C. ....	3911578	▲K080660HD
Belt - Fan & Alt.; W/67 5/8" Belt O.C. ....	3911567	▲K080670HD
Belt - Fan & Alt.; W/68 1/8" Belt O.C. ....	3911579	▲K080675HD
Hose - Upper .....		②<20731
Hose - Lower - Eng. To Pipe .....		②<21473
Hose - Lower - Pipe To Rad. ....		●26507
<b>195 Workhorse</b>		
<b>Cummins 6-Cyl. 505 Diesel</b>		
1992-1990		
Belt - A.C.; W/40 3/8" Belt O.C. ....	303315134	▲9400HD
Belt - Fan & Alt.; W/66 5/8" Belt O.C. ....	3911578	▲K080660HD
Belt - Fan & Alt.; W/67 5/8" Belt O.C. ....	3911567	▲K080670HD
Belt - Fan & Alt.; W/68 1/8" Belt O.C. ....	3911579	▲K080675HD
Hose - Upper .....		②<20731
Hose - Lower - Eng. To Pipe .....		21901
Hose - Lower - Pipe To Rad. ....		●26507
<b>1355</b>		
<b>Fiat 4-Cyl. 190 Diesel</b>		
1971-1969		
Belt - A.C. ....		③▲9580HD
Belt - Fan & Alt. ....		②▲9580HD
Hose - Upper .....		●26612
Hose - Lower .....		24244
Hose - By Pass .....		24232
<b>1555</b>		
<b>Oliver 6-Cyl. 232</b>		
1975-1969		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162123A	7445
Belt - P.S. ....	157176AA	7290
Hose - Lower - Eng. To Pipe .....		②<20520
Hose - Lower - Pipe To Rad. ....		24234
<b>Oliver 6-Cyl. 232 Diesel</b>		
1975-1969		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	158679A	7450
Belt - P.S. ....	157177AA	7375
Hose - Lower .....		24228

②Two Required ③Three Required <Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>WHITE - Continued</b>		
<b>1655</b>		
<b>Oliver 6-Cyl. 265</b>		
1975-1969		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	158679A	7450
Belt - P.S. ....	157176AA	7290
Hose - Upper .....		⊗20611
		or ●26508
Hose - Lower - Eng. To Pipe .....		24228
Hose - Lower - Pipe To Rad. ....		⊗20520
<b>Oliver 6-Cyl. 283 Diesel</b>		
1975-1969		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt.; W/Dual Belts; W/46 1/8" Belt O.C. ....	162071A	②7460
Belt - Fan & Alt.; W/Dual Belts; W/47 1/4" Belt O.C. ....	②▲9470HD	7460
Belt - Fan & Alt.; W/Single Belt .....	157680A	7460
Belt - P.S. ....	157177A	7375
Hose - Upper .....		⊗20611
		or ●26508
Hose - Lower - Eng. To Pipe .....		24228
Hose - Lower - Pipe To Rad. ....		⊗20520
<b>1755</b>		
<b>Oliver 6-Cyl. 283</b>		
1975-1970		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460
Belt - P.S. ....	157176A	7290
Hose - Upper; W/Row Crop Style .....		●26509
Hose - Upper; W/Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>Oliver 6-Cyl. 310 Diesel</b>		
1975-1970		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460
Belt - P.S.; W/A.C. ....	103926A	7250
Belt - P.S.; W/O A.C. ....	168052A	7417
Hose - Upper; W/Row Crop, Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>1855</b>		
<b>Oliver 6-Cyl. 310</b>		
1975-1969		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460
Belt - P.S. ....	157176AA	7290
Hose - Upper; W/Row Crop Style .....		●26509
Hose - Upper; W/Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>Oliver 6-Cyl. 310 Diesel</b>		
1975-1969		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	162071A	②7460
Belt - P.S.; W/A.C. ....	103926A	7250
Belt - P.S.; W/O A.C. ....	168052A	7417
Hose - Upper; W/Row Crop Style .....		●26509
Hose - Upper; W/Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234
Hose - Lower - Pipe To Rad. ....		24234
<b>1955</b>		
<b>Waukesha 6-Cyl. 310 Diesel</b>		
1974-1969		
Belt - A.C. ....	167897A	7480
Belt - Fan & Alt. ....	157680A	②7460
Belt - P.S.; W/A.C. ....	103926A	7250
Belt - P.S.; W/O A.C. ....	168052A	7417
Hose - Upper; W/Row Crop Style .....		●26509
Hose - Upper; W/Wheatland Style .....		●26508
Hose - Lower - Eng. To Pipe .....		24234

Application	OEM No.	Our No.
<b>WHITE - Continued</b>		
<b>1955 - Continued</b>		
<b>Waukesha 6-Cyl. 310 Diesel - Continued</b>		
1974-1969 - Continued		
Hose - Lower - Pipe To Rad. ....		24234
<b>6065</b>		
<b>SLH 4-Cyl. 244 Diesel</b>		
2001-1992		
Hose - Upper .....		●25478
Hose - Lower - Pipe To Rad. ....		24220
Hose - By Pass .....		28442
<b>6085</b>		
<b>SLH 4-Cyl. 244 Diesel</b>		
1997-1992		
Hose - Lower - Pipe To Rad. ....		24220
Hose - By Pass .....		28442
<b>6090</b>		
<b>SLH 4-Cyl. 244 Diesel</b>		
2000-1995		
Hose - Lower - Eng. To Pipe .....		24222
<b>6105</b>		
<b>SLH 6-Cyl. 366 Diesel</b>		
1997-1992		
Hose - Upper .....		●26507
Hose - Lower - Eng. To Pipe .....		24448
Hose - Lower - Pipe To Rad. ....		24456
<b>6125</b>		
<b>Cummins 6-Cyl. 359 Diesel</b>		
1997-1993		
Belt - Serpentine .....	3911559	▲K080620HD
Belt - Fan To A.C. ....		▲9470HD
Hose - Upper .....		●26524
Hose - Lower - Eng. To Pipe .....		21901
<b>6175; 6195</b>		
<b>Cummins 6-Cyl. 505 Diesel</b>		
1999-1993		
Belt - Serpentine .....	3911559	▲K080620HD
Belt - Fan To A.C. ....		▲9470HD
Hose - Upper .....		●26524
Hose - Lower - Eng. To Pipe .....		21901
<b>FB21</b>		
<b>Iseki 3-Cyl. 71 Diesel</b>		
1988-1986		
Belt - Fan & Alt. ....		7375
Hose - Upper .....		⊗21942
Hose - Lower .....		⊗21942
<b>FB31</b>		
<b>Iseki 3-Cyl. 91 Diesel</b>		
1988-1986		
Belt - Fan & Alt. ....	5136710400	▲9400HD
Hose - Upper .....		●25251
<b>FB37</b>		
<b>Iseki 4-Cyl. 111 Diesel</b>		
1988-1986		
Belt - Fan & Alt. ....		▲9420HD
Hose - Upper .....		●25251
<b>WOODS &amp; COPELAND</b>		
<b>320C</b>		
<b>Cummins V-8 903 Diesel</b>		
1983-1980		
Belt - Fan & Alt. ....	178653	6926
Belt - Fan & W.P. ....	202046	③▲9580HD
Belt - Fan To A.C. ....	178386	▲9476HD

②Two Required ③Three Required ⊗Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>WOODS &amp; COPELAND - Continued</b>		
<b>320C - Continued</b>		
<b>Cummins V-8 903 Diesel - Continued</b>		
1983-1980 - Continued		
Hose - Upper .....	②	●26525
Hose - Lower .....		24244
<b>YANMAR</b>		
<b>YM135</b>		
<b>Yanmar 2-Cyl. 38 Diesel</b>		
1979-1976		
Belt - Fan .....		7290
Hose - Lower .....	☞	<21171
<b>YM140</b>		
<b>Yanmar 2-Cyl. 39 Diesel</b>		
1992-1984		
Belt - Fan & Alt. ....	121522	▲9360HD
<b>YM146</b>		
<b>Yanmar 2-Cyl. 39 Diesel</b>		
1993-1983		
Belt - Fan & Alt. ....		▲9341HD
Hose - Upper .....		24224
Hose - Lower .....	☞	<20661
		or ●25251
<b>YM147</b>		
<b>Yanmar 2-Cyl. 39 Diesel</b>		
1992-1984		
Belt - Fan & Alt. ....	121522	▲9360HD
<b>YM155</b>		
<b>Yanmar 2-Cyl. 40 Diesel</b>		
1979-1976		
Belt - Fan .....		7290
<b>YM165</b>		
<b>Yanmar 2-Cyl. 40 Diesel</b>		
1986-1980		
Belt - Fan .....	12406442290	▲9290HD
<b>YM169</b>		
<b>Yanmar 3-Cyl. 54 Diesel</b>		
1989-1986		
Belt - Fan & Alt. ....	124064	▲9290HD
<b>YM180</b>		
<b>Yanmar 3-Cyl. 54 Diesel</b>		
1992-1983		
Belt - Fan & Alt. ....	121023	▲9335HD
<b>YM186</b>		
<b>Yanmar 3-Cyl. 54 Diesel</b>		
1986-1980		
Belt - Fan & Alt. ....	12102342290	▲9335HD
Hose - Upper .....	☞	<21029
Hose - Lower .....	☞	<20774
		or ●25251
<b>YM187</b>		
<b>Yanmar 3-Cyl. 54 Diesel</b>		
1989-1986		
Belt - Eng. To Deck .....	3316808	6732
Belt - Fan & Alt.; W/33 1/2" Belt O.C. ....	121023	▲9335HD
Belt - Fan & Alt.; W/35" Belt O.C. ....		▲9350HD
<b>YM195</b>		
<b>Yanmar 2-Cyl. 61 Diesel</b>		
1980-1977		
Belt - Fan & Alt. ....		▲9380HD
Belt - W.P. ....	124240	▲9390HD

Application	OEM No.	Our No.
<b>YANMAR - Continued</b>		
<b>YM220</b>		
<b>Yanmar 3-Cyl. 69 Diesel</b>		
1993-1982		
Belt - Fan & Alt. ....	12102342290	▲9335HD
Hose - Upper .....		☞<21029
Hose - Lower .....		☞<20774
		or ●25251
<b>YM226</b>		
<b>Yanmar 3-Cyl. 69 Diesel</b>		
1993-1981		
Belt - Fan & Alt. ....	12102342290	▲9335HD
Hose - Upper .....		☞<21029
Hose - Lower .....		☞<20774
		or ●25251
<b>YM240</b>		
<b>Yanmar 2-Cyl. 70 Diesel</b>		
1981-1977		
Belt - Fan & Alt. ....		▲9380HD
Belt - W.P. ....	124240	▲9390HD
<b>YM330</b>		
<b>Yanmar 3-Cyl. 91 Diesel</b>		
1991-1978		
Belt - Fan & Alt. ....	124756	▲9380HD
Belt - W.P. ....	124240	▲9390HD
<b>YM336</b>		
<b>Yanmar 3-Cyl. 91 Diesel</b>		
1993-1980		
Belt - Fan & Alt. ....		▲9412HD
Hose - Upper .....		☞<21029
Hose - Lower .....		☞<20774
		or ●25251
<b>ZETOR</b>		
<b>3320</b>		
<b>Zetor 3-Cyl. 164 Diesel</b>		
2001-1993		
Belt - Fan & Alt. ....		AX44
<b>3340</b>		
<b>Zetor 3-Cyl. 164 Diesel</b>		
2001-1993		
Belt - Fan & Alt. ....		AX44
Hose - Upper - Eng. To Thermostat .....		24220
Hose - Upper - Thermostat To Intake Manifold .....		24226
Hose - Upper - Thermostat To Rad. ....		24224
<b>3520</b>		
<b>Zetor 3-Cyl. 143 Diesel</b>		
1996-1992		
Hose - Upper - Eng. To Thermostat .....		24222
Hose - Upper - Thermostat To Intake Manifold .....		☞<21528
Hose - Upper - Thermostat To Rad. ....		24224
<b>4340</b>		
<b>Zetor 4-Cyl. 239 Diesel</b>		
2004-1994		
Hose - Upper - Eng. To Thermostat .....		24220
Hose - Upper - Thermostat To Intake Manifold .....		24226
Hose - Upper - Thermostat To Rad. ....		24224
<b>5211; 5245</b>		
<b>Zetor 3-Cyl. 164 Diesel</b>		
1992-1985		
Belt - Fan & Alt. ....		TR22474
Hose - Upper - Eng. To Thermostat .....		24222
Hose - Upper - Intake Manifold To Thermostat .....		24224
Hose - Upper - Thermostat To Rad. ....		24224

②Two Required ☞Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

Agricultural Equipment





Application	OEM No.	Our No.
<b>ZETOR - Continued</b>		
<b>6211</b>		
<b>Zetor 4-Cyl. 211 Diesel</b>		
1992-1986		
Belt - Fan & Alt. ....		TR22474
Hose - Upper - Eng. To Thermostat .....		24222
Hose - Upper - Intake Manifold To Thermostat .....		24224
Hose - Upper - Thermostat To Rad. ....		24224
<b>6245</b>		
<b>Zetor 4-Cyl. 211 Diesel</b>		
1992-1985		
Belt - Fan & Alt. ....		TR22474
Hose - Upper - Eng. To Thermostat .....		24222
Hose - Upper - Intake Manifold To Thermostat .....		24224
Hose - Upper - Thermostat To Rad. ....		24224
<b>6340</b>		
<b>Zetor 4-Cyl. 239 Diesel</b>		
2001-1994		
Hose - Upper - Eng. To Thermostat .....		24220
Hose - Upper - Thermostat To Intake Manifold .....		24226
Hose - Upper - Thermostat To Rad. ....		24224
<b>7211; 7245</b>		
<b>Zetor 4-Cyl. 219 Diesel</b>		
1989-1985		
Belt - Fan & Alt. ....		TR22474
Hose - Upper - Eng. To Thermostat .....		24222
Hose - Upper - Intake Manifold To Thermostat .....		24224
Hose - Upper - Thermostat To Rad. ....		24224
<b>7320</b>		
<b>Zetor 4-Cyl. 239 Diesel</b>		
2004-1993		
Belt - Fan & Alt. ....		AX44
<b>7321</b>		
<b>Zetor 4-Cyl. 239 Diesel</b>		
2005-1997		
Belt - Fan & Alt. ....		②AX42
<b>7340</b>		
<b>Zetor 4-Cyl. 239 Diesel</b>		
2004-1993		
Belt - Fan & Alt. ....		AX44
<b>7341</b>		
<b>Zetor 4-Cyl. 239 Diesel</b>		
2005-1997		
Belt - Fan & Alt. ....		②AX42
<b>7711</b>		
<b>Zetor 4-Cyl. 239 Diesel</b>		
1992-1986		
Belt - Fan & Alt. ....		TR22474
Hose - Upper - Eng. To Thermostat .....		24222
Hose - Upper - Intake Manifold To Thermostat .....		24224
Hose - Upper - Thermostat To Rad. ....		24224
<b>7745</b>		
<b>Zetor 4-Cyl. 239 Diesel</b>		
1996-1988		
Belt - Fan & Alt. ....		TR22474
Hose - Upper - Eng. To Thermostat .....		24222
Hose - Upper - Intake Manifold To Thermostat .....		24224
Hose - Upper - Thermostat To Rad. ....		24224
<b>8111; 8145</b>		
<b>Zetor 4-Cyl. 278 Diesel</b>		
1991-1985		
Belt - Fan & Alt. ....		②7480

Application	OEM No.	Our No.
<b>ZETOR - Continued</b>		
<b>9520; 9540</b>		
<b>Zetor 4-Cyl. 254 Diesel</b>		
1996-1991		
Hose - Upper .....	②-20957	or ●26603
Hose - Lower - Pipe To Rad. ....		24224
<b>10111; 10145</b>		
<b>Zetor 4-Cyl. 278 Diesel</b>		
1991-1985		
Belt - A.C.; W/44" Belt O.C. ....	②♣9435HD	
Belt - A.C.; W/47 3/8" Belt O.C. ....	♣9470HD	
Belt - Fan & Alt. ....	②7485	
<b>12111</b>		
<b>Zetor 6-Cyl. 418 Diesel</b>		
1994-1985		
Belt - A.C.; W/44" Belt O.C. ....	②♣9435HD	
Belt - A.C.; W/47 3/8" Belt O.C. ....	♣9470HD	
Belt - Fan & Alt. ....	②7485	
<b>12145</b>		
<b>Zetor 6-Cyl. 418 Diesel</b>		
1992-1983		
Belt - A.C.; W/44" Belt O.C. ....	②♣9435HD	
Belt - A.C.; W/47 3/8" Belt O.C. ....	♣9470HD	
Belt - Fan & Alt. ....	②7485	
<b>16145</b>		
<b>Zetor 6-Cyl. 418 Diesel</b>		
1990-1985		
Belt - A.C.; W/44" Belt O.C. ....	②♣9435HD	
Belt - A.C.; W/47 3/8" Belt O.C. ....	♣9470HD	
Belt - Fan & Alt. ....	②7485	

②Two Required ③Cut to Fit ●Flexible Coolant Hose ♣Standard Belt May Also Be Available

Manufacturers' Part Number Shown for Reference Only

Application	OEM No.	Our No.
<b>CASE</b>		
<b>955</b>		
<b>Case 4-Cyl. 159</b>		
1972		
Belt - Fan & Alt. ....		▲9630HD
<b>1075SP</b>		
<b>Chrysler 6-Cyl. 170</b>		
1973-1972		
Belt - Fan & Alt. ....	1632586	◎7417
Belt - Gov. ....	3814009	7450
Hose - Upper ....		≡<21794
		or ●25480
Hose - Lower ....		●25808
<b>1155</b>		
<b>Case 4-Cyl. 159</b>		
1972		
Belt - Fan & Alt. ....		▲9480HD
Hose - Lower ....		●26501
<b>Case 4-Cyl. 188 Diesel</b>		
1972		
Belt - Fan & Alt. ....		▲9480HD
Hose - Lower ....		●26501
<b>1275</b>		
<b>Chrysler 6-Cyl. 225</b>		
1973-1972		
Belt - Fan & Alt. ....		7417
Belt - Gov. ....		7470
Hose - Upper ....		≡<21794
		or ●25476
Hose - Lower ....		≡<21794
		or ●25480
<b>CASE IH</b>		
<b>8830</b>		
<b>Case 4-Cyl. 390</b>		
1995-1987		
Belt - A.C. ....	700708217	▲9465HD
Hose - Upper ....		●26611
<b>8840</b>		
<b>Case 4-Cyl. 239 Diesel</b>		
1998-1987		
Belt - A.C. ....	700709214	▲9440HD
Belt - Fan ....	J911578	▲K080660HD
Hose - Upper; Strt. Hose ....		◎24228
Hose - Lower; Molded Hose ....		●26515
<b>8850HP</b>		
<b>Case 6T590 Diesel</b>		
1998-1995		
Hose - Upper ....		●26512
Hose - Lower ....		●26522
<b>HESSTON</b>		
<b>420</b>		
<b>Chrysler 6-Cyl. 170</b>		
1976-1970		
Belt - Fan & Alt. ....		7417
Belt - Hyd. Pump ....		7455
Hose - Upper ....		≡<21794
		or ●25480
Hose - Lower ....		●25808

Application	OEM No.	Our No.
<b>HESSTON - Continued</b>		
<b>500</b>		
<b>Ford 4-Cyl. 172</b>		
1967-1963		
Belt - Fan & Gen. ....	C6TZ 8620 B	▲9420HD
Hose - Upper ....		24220
Hose - Lower ....		20065
<b>520</b>		
<b>Chrysler 6-Cyl. 170</b>		
1974-1973		
Belt - Fan & Alt. ....		7417
Belt - Hyd. Pump ....		7455
Hose - Upper ....		≡<21794
		or ●25480
Hose - Lower ....		●25808
<b>600</b>		
<b>Ford 4-Cyl. 172</b>		
1969-1967		
Belt - Fan & Gen. ....		▲9415HD
Hose - Upper ....		24220
Hose - Lower ....		≡<21794
		or ●25480
<b>620</b>		
<b>Chrysler 6-Cyl. 225</b>		
1973-1970		
Belt - A.C. ....	855528	▲9510HD
Belt - Fan & Alt. ....	1532508	7417
Belt - Hyd. Pump ....	2407321	7470
Hose - Upper ....		≡<21794
		or ●25480
Hose - Lower ....		≡<21660
<b>6200</b>		
<b>Perkins</b>		
1979-1976		
Belt - Fan & Alt. ....	2951919	7417
Hose - Upper ....		≡<21794
		or ●25474
Hose - Lower ....		●25808
<b>6400</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1979-1975		
Belt - A.C. ....	855528	▲9510HD
Belt - Fan & Alt.; W/41 5/8" Belt O.C. ....	2951919	7417
Belt - Fan & Alt.; W/43 1/8" Belt O.C. ....		7430
Belt - Fan & Alt.; W/51 3/8" Belt O.C. ....	855528	▲9510HD
Belt - Gov. ....	2951893	7470
Hose - Upper ....		≡<20416
		or ●25473
Hose - Lower ....		●25808
<b>6450</b>		
<b>Chrysler 6-Cyl. 225</b>		
1988-1980		
Belt - Fan & Alt. ....	955510	7410
Belt - Gov. ....	857029	7470
<b>6550</b>		
<b>Chrysler 6-Cyl. 225</b>		
1988-1980		
Belt - Fan & Alt. ....	856518	▲9525HD
Belt - Hyd. Pump ....	856591	▲9570HD
<b>Perkins 4-Cyl. 236 Diesel</b>		
1988-1980		
Belt - A.C. ....		▲9570HD
Belt - Fan & Alt. ....		▲9510HD

◎Two Required ≡<Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>HESSTON - Continued</b>		
<b>6550 - Continued</b>		
<b>Perkins 4-Cyl. 236 Diesel - Continued</b>		
1988-1980 - Continued		
Hose - Upper .....		≅21379 or ●26511
<b>6555</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1988-1986		
Belt - A.C. ....		▲9570HD
Belt - Fan & Alt. ....		▲9510HD
Hose - Upper .....		≅20046 or ●26502
<b>6600</b>		
<b>Chrysler 6-Cyl. 225</b>		
1978-1975		
Belt - Fan & Alt. ....	3671074	7525
Belt - Gov. ....	2951893	7470
Belt - W.P. ....	3671259	7390
Hose - Upper .....		●25482
Hose - Lower .....		●25527
<b>Perkins 4-Cyl. 236 Diesel</b>		
1978-1975		
Belt - Fan & Alt. ....	855528	▲9510HD
Hose - Upper .....		≅20046 or ●26502
Hose - Lower .....		●25482
<b>6650</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1988-1980		
Belt - A.C. ....		▲9570HD
Belt - Fan & Alt. ....		▲9510HD
Hose - Upper .....		≅20611
<b>8200</b>		
<b>Cummins 4-Cyl. 3.9 L Diesel</b>		
1998-1987		
Belt - Fan To A.C. ....		▲9465HD
Belt - Fan, Alt. & Idler .....	700708233	▲K080537HD
Hose - Upper .....		●26511
<b>8400</b>		
<b>Cummins 4-Cyl. 3.9 L Diesel</b>		
1997-1987		
Belt - Serpentine .....	700708547	▲K080657HD
Belt - Fan To A.C. ....		▲9455HD
Hose - Upper .....		②24228
Hose - Lower .....		●26515
<b>INTERNATIONAL HARVESTER</b>		
<b>161; 163</b>		
<b>IH C123</b>		
1956-1936		
Belt - Fan .....	271667R1	TR24315
Belt - Fan & W.P. ....	273889R1	TR26341
Belt - Gen. ....	49291D	9260
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>IH C135</b>		
1956-1936		
Belt - Fan & Gen. ....	367697R1	7417
Hose - Upper .....		24232
Hose - Lower .....		24232
<b>201</b>		
<b>IH BD144C</b>		
1969-1962		
Belt - Fan .....	3040315R2	TR22363
Belt - Gen. ....	704449R1	▲9309HD

Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>201 - Continued</b>		
<b>IH C135</b>		
1969		
Belt - Fan & Gen. ....	367697R1	7417
<b>210</b>		
<b>IH C153</b>		
1977-1972		
Belt - Fan & Gen. ....	352095C1	▲9510HD
Hose - Upper .....		●26514
<b>IH C175</b>		
1977-1972		
Belt - Fan & Gen. ....	352095C1	▲9510HD
Hose - Upper .....		●26514
<b>IH C232</b>		
1977-1972		
Hose - Upper .....		●26514
<b>230</b>		
<b>IH C153</b>		
1979-1976		
Belt - Fan & Gen. ....	352095C1	▲9510HD
<b>IH C175</b>		
1979-1976		
Belt - Fan & Gen. ....	352095C1	▲9510HD
<b>275</b>		
<b>IH C153</b>		
1976-1972		
Belt - Fan & Gen. ....	352095C1	▲9510HD
Belt - Knife Drive .....	558141R1	C101
Hose - Upper .....		●26515
<b>IH C175</b>		
1976-1972		
Belt - Fan & Gen. ....	352095C1	▲9510HD
Belt - Knife Drive .....	558141R1	C101
Hose - Upper .....		●26515
<b>IH C232</b>		
1976-1972		
Belt - Knife Drive .....	558141R1	C101
Hose - Upper .....		●26515
<b>375</b>		
<b>IH C232</b>		
1976-1972		
Belt - Fan & Alt. ....	306219C2	7370
Belt - Fan & Gen. ....	352095C1	▲9510HD
Belt - Knife Drive .....	558141R1	C101
Hose - Upper .....		≅21794 or ●25477
<b>IH D206 Diesel</b>		
1976-1972		
Belt - Fan & Alt. ....	676835R1	▲9520HD
Belt - Fan & Gen. ....	352095C1	▲9510HD
Belt - Knife Drive .....	558141R1	C101
Hose - Upper .....		●25473
Hose - By Pass .....		≅20573
<b>4000</b>		
<b>IH 6-Cyl. 258</b>		
1985-1978		
Belt - A.C. ....	488082R2	▲9520HD
Belt - Fan & Alt.; Ser. No. 6004 & Before .....	403348R1	▲9463HD
Belt - Fan & Alt.; Ser. No. 6005 & After .....	826761C1	▲9390HD
Belt - Gov. ....	829627C1	7541
Hose - Upper .....		≅21794 or ●25477
Hose - Lower .....		●26504

②Two Required ≅Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available

# WINDROWERS



Application	OEM No.	Our No.
<b>INTERNATIONAL HARVESTER - Continued</b>		
<b>5000</b>		
<b>IH 4-Cyl. 239 Diesel</b>		
1985-1978		
Belt - A.C.; W/46 3/8" Belt O.C. ....	829921C1	▲9463HD
Belt - A.C.; W/54 5/8" Belt O.C. ....	829920C1	▲9540HD
Belt - Fan & Alt. ....	280210C2	▲9540HD
<b>5500</b>		
<b>IH 4-Cyl. 239 Diesel</b>		
1979-1978		
Belt - A.C.; W/46 3/8" Belt O.C. ....	829921C1	▲9463HD
Belt - A.C.; W/54 5/8" Belt O.C. ....	829920C1	▲9540HD
Belt - Fan & Alt. ....	280210C2	▲9540HD
<b>JOHN DEERE</b>		
<b>215</b>		
<b>John Deere 4-Cyl.</b>		
1964-1961		
Belt - Fan & Gen. ....	T12042T	7410
Hose - Upper ....		●25472
Hose - Lower ....		●25476
<b>800SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1980-1972		
Belt - Fan & Alt. ....	E50973	▲9435HD
Belt - Gov. ....	E57428	7465
Hose - Upper ....		●25473
<b>830SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1980-1972		
Belt - Fan & Alt. ....	E50973	▲9435HD
Belt - Gov. ....	E57428	7465
Hose - Upper ....		●25476
Hose - Lower ....		●25484
<b>880</b>		
<b>John Deere 51EA</b>		
1970		
Belt - Fan & Alt. ....	T20334	TR22474
Hose - Upper ....		②<21794
		or ●25480
Hose - Lower ....		●26509
Hose - By Pass ....		28439
<b>2250SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1978-1973		
Belt - Fan & Alt. ....	H63772	▲9540HD
Belt - Gov. ....	E57428	7465
Belt - W.P.; W/A.C. ....	E53936	▲9690HD
Belt - W.P.; W/O A.C. ....	E52878	7390
<b>2270SP</b>		
<b>John Deere 4-Cyl. 219</b>		
1978-1973		
Belt - A.C. ....	E50973	▲9435HD
Belt - Fan & Alt. ....	T20334T	TR24476
Hose - By Pass ....		②<20338
<b>2280SP</b>		
<b>John Deere 4-Cyl. 219</b>		
1985-1978		
Belt - A.C. ....	E50973	▲9435HD
Belt - Fan & Alt. ....	T20334T	TR24476
Hose - By Pass ....		②<20338
<b>2320SP</b>		
<b>Chrysler 6-Cyl. 225</b>		
1985-1980		
Belt - Fan ....	E50973	▲9435HD

Application	OEM No.	Our No.
<b>JOHN DEERE - Continued</b>		
<b>2320SP - Continued</b>		
<b>Chrysler 6-Cyl. 225 - Continued</b>		
1985-1980 - Continued		
Belt - Gov. ....	E57428	7465
Belt - Platform J.S. Drive ....	E56262	3/A55
<b>2360</b>		
<b>Chrysler 6-Cyl. 225</b>		
1995-1984		
Belt - Gov. ....	E57428	7465
<b>John Deere 4-Cyl. 219 Diesel</b>		
1995-1984		
Belt - Fan & Alt. ....	T25130	TR22495
<b>2420</b>		
<b>John Deere 4-Cyl. 219 Diesel</b>		
1985-1980		
Belt - A.C. ....	E50973	▲9435HD
Belt - Fan & Alt. ....		TR22495
Belt - Platform J.S. Drive ....	E56262	3/A55
Hose - Upper ....		②<20065
Hose - By Pass ....		②28441
<b>3430SP</b>		
<b>John Deere 4-Cyl. 239 Diesel</b>		
1996-1992		
Belt - A.C. ....		▲9463HD
Belt - Fan & Alt. ....		TR22534
Belt - Platform J.S. Drive ....	E56262	3/A55
Hose - Upper ....		②<21794
		or ●25474
1991		
Belt - A.C. ....		▲9463HD
Belt - Fan & Alt. ....		TR22534
Hose - Upper ....		②<21794
		or ●25474
1990-1985		
Belt - A.C. ....		▲9463HD
Belt - Fan & Alt. ....		TR22534
Belt - Platform J.S. Drive ....	E56262	3/A55
Hose - Upper ....		②<21794
		or ●25474
<b>3830SP</b>		
<b>John Deere 4-Cyl. 239 Diesel</b>		
1996-1985		
Belt - A.C. ....	N117674	▲9463HD
Belt - Fan & Alt. ....	E75596	TR22533
Hose - Upper ....		●25484
Hose - By Pass ....		28441
<b>MACDON</b>		
<b>7000</b>		
<b>Chrysler 6-Cyl. 225</b>		
1993-1985		
Belt - A.C. ....	K240341	7483
Belt - Fan & Alt. ....	K240071	7590
Belt - Gov. ....	K243341	7460
<b>9000</b>		
<b>Cummins 4-Cyl. 3.9 L Diesel</b>		
1995-1994		
Belt - A.C.; W/41 1/2" Belt O.C. ....		▲9412HD
Belt - A.C.; W/48 5/8" Belt O.C. ....		▲9480HD
Belt - Fan & Alt. ....		▲K080560HD
Hose - Lower ....		●26611
<b>9200</b>		
<b>Cummins 4-Cyl. 3.9 L Diesel</b>		
1999-1996		
Belt - Fan & Alt. ....		▲K080560HD

②Two Required ③Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Application	OEM No.	Our No.
<b>MACDON - Continued</b>		
<b>9352</b>		
Cummins 4-Cyl. 3.9 L Diesel		
2006-2001		
Belt - A.C. ....	21964	▲9412HD
<b>MASSEY FERGUSON</b>		
<b>34SP</b>		
Continental		
1980-1975		
Belt - Fan & Gen. ....	223336M2	▲9447HD
<b>36SP</b>		
Chevrolet 6-Cyl. 292		
1982-1976		
Belt - Fan & Alt. ....	833960M1	7400
Belt - Gov. ....	238891M1	7555
Chrysler 6-Cyl. 225		
1982-1976		
Belt - Fan & Alt. ....	834063M1	7560
Belt - Gov. ....	235199M1	7450
Hose - Upper .....		≧20168
		or ●25473
Hose - Lower .....		●25482
<b>44</b>		
Continental		
1982-1976		
Belt - Fan & Gen. ....	223336M2	▲9447HD
<b>655</b>		
Chrysler 6-Cyl. 225		
1978-1974		
Belt - Alt. ....		7417
Belt - Fan ....	1044074M1	7490
Belt - Gov. ....	K17951	7500
Hose - Upper .....		20473
<b>775</b>		
Chrysler 6-Cyl. 225		
1984-1978		
Belt - Fan ....	K194681	7417
Belt - Gov. ....	K179511	7490
Hose - By Pass .....		28441
<b>785</b>		
Chrysler 6-Cyl. 225		
1986-1984		
Hose - By Pass .....		28441
<b>885</b>		
Chrysler 6-Cyl. 225		
1991-1983		
Belt - Alt. ....	1044087M1	7417
Belt - Gov. ....	1056470M1	7460
Perkins 4-Cyl. 203 Diesel		
1991-1983		
Belt - Fan & Alt. ....	1056522M1	▲9510HD
Hose - Upper .....		24228
<b>NEW HOLLAND</b>		
<b>905</b>		
Continental Y112		
1963		
Belt - Fan .....		TR22358
Belt - Hyd. Pump .....		TR22534
Hose - Upper .....		24228
Hose - Lower .....		24228

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>905 - Continued</b>		
Ford 4-Cyl. 172		
1963		
Belt - Fan & Gen. ....		▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		20065
		or ●25473
Ford 4-Cyl. 172 Diesel		
1963		
Belt - Fan & Gen. ....		▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		20065
		or ●25473
Ford 4-Cyl. 200		
1963		
Belt - Fan & Gen. ....		▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		20065
		or ●25473
Ford 4-Cyl. 256		
1963		
Belt - Fan & Gen. ....		▲9415HD
Hose - Upper .....		24220
Hose - Lower .....		20065
		or ●25473
<b>910; 912</b>		
Ford 4-Cyl. 256 Diesel		
1977-1971		
Belt - Fan & Alt. ....		▲9540HD
Hose - Upper .....		●25528
Hose - Lower .....		●26612
Ford 6-Cyl. 250		
1977-1971		
Belt - A.C. ....	133929	▲9430HD
Belt - Fan .....	259346	▲9480HD
Belt - Gov. ....	259348	7470
Belt - W.P. & Alt. ....	259347	7417
Hose - Upper .....		●26611
Hose - Lower .....		●25528
<b>1100</b>		
Perkins 4-Cyl. 236 Diesel		
1991-1975		
Belt - A.C. ....	259346	▲9480HD
Belt - Draper Drive .....	219435	A50
Belt - Fan & Alt. ....	633337	②▲9525HD
Belt - Gov. ....	219349	7315
Hose - Upper .....		≧20957
<b>1110</b>		
Ford 6-Cyl. 200		
1983-1975		
Belt - Gov. ....	219349	7315
Belt - W.P. & Alt. ....		②7340
Hose - Upper .....		≧20957
Hose - Lower .....		●25480
<b>1112</b>		
Ford 6-Cyl. 250		
1979		
Belt - A.C. ....	133929	▲9430HD
Belt - Auger & Reel Drive .....	9622032	C106
Belt - Fan .....	259346	▲9480HD
Belt - Gov. ....	259348	7470
Belt - W.P. & Alt. ....	577982	7420
Hose - Upper .....		●26611
Hose - Lower .....		●25530
1978-1975		
Belt - A.C. ....	133929	▲9430HD
Belt - Auger & Reel Drive .....	9622032	C106
Belt - Fan .....	259346	▲9480HD

②Two Required ≧Cut to Fit ●Flexible Coolant Hose ▲Standard Belt May Also Be Available





Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>1112 - Continued</b>		
<b>Ford 6-Cyl. 250 - Continued</b>		
1978-1975 - Continued		
Belt - Gov. ....	259348	7470
Belt - W.P. & Alt. ....		7420
Hose - Upper .....		●26611
Hose - Lower .....		●25530
<b>1114</b>		
<b>Ford 4-Cyl. 256 Diesel</b>		
1981-1979		
Hose - Upper .....		●25532
<b>Ford 6-Cyl. 250</b>		
1981-1979		
Belt - A.C. ....	133929	▲9430HD
Belt - Auger & Reel Drive .....	9622032	C106
Belt - Fan .....	259346	▲9480HD
Belt - Gov. ....	259348	7470
Belt - W.P. & Alt. ....	577982	7420
Hose - Upper .....		●26611
Hose - Lower .....		●25530
<b>1116</b>		
<b>Perkins 4-Cyl. 236 Diesel</b>		
1987-1980		
Belt - Alt. ....	708712	▲9545HD
Belt - Header .....	643307	2/B93
<b>1118</b>		
<b>Ford 4-Cyl. 256 Diesel</b>		
1992		
Belt - A.C. ....		▲9490HD
Belt - Alt. ....	708712	②▲9545HD
Belt - Header .....	643307	2/B93
Belt - Reel Drive .....	9622032	C106
Hose - Upper .....		●25528
Hose - Lower .....		●26612
1991-1986		
Belt - A.C. ....		▲9490HD
Belt - Alt. ....	708712	②▲9545HD
Belt - Header .....	643307	2/B93
Hose - Upper .....		●25528
Hose - Lower .....		●26612
<b>1495</b>		
<b>Ford 6-Cyl. 200</b>		
1986-1975		
Belt - A.C. ....	572981	▲9430HD
Belt - Fan .....	219133	7320
Belt - Fan & Alt. ....		②7340
Belt - W.P. & Gov. ....		7312
Hose - Upper .....		●26505
Hose - Lower .....		●25482
<b>1499</b>		
<b>Ford 4-Cyl. 256 Diesel</b>		
1992-1987		
Belt - A.C. ....		▲9435HD
Belt - Fan & Alt. ....		▲9550HD
Hose - Upper .....		●25477
<b>2450; 2550</b>		
<b>Ford 4-Cyl. 304 Diesel</b>		
1998-1992		
Hose - Upper .....		●25478
<b>HW300; HW320</b>		
<b>Genesis 4-Cyl. 304 Diesel</b>		
2004-1998		
Tensioner Assy. ....	87801689	38672

Application	OEM No.	Our No.
<b>NEW HOLLAND - Continued</b>		
<b>HW340</b>		
<b>Genesis 6-Cyl. 166 H.P. Diesel</b>		
2004-1998		
Belt - Serpentine .....	86529107	▲K080797HD
<b>OWATONNA</b>		
<b>265</b>		
<b>Ford 6-Cyl. 3.3 L</b>		
Belt - A.C. ....		▲9447HD
Belt - Fan & Alt. ....		▲9350HD
Belt - Gov. ....		7312
Hose - Upper - Eng. To Pipe .....		●26612
Hose - Lower - Eng. To Pipe .....		●26612
<b>VERSATILE</b>		
<b>330</b>		
<b>Ford 4-Cyl. 122</b>		
1984-1970		
Belt - Fan & Alt. ....		②7360
Belt - Fan & Gov. ....		▲9500HD
Hose - Upper .....		●25476
Hose - Lower .....		●25487
<b>440</b>		
<b>Ford 6-Cyl. 200</b>		
1975-1972		
Belt - Fan & Alt. ....	C5DE 8620 C	7340
Belt - Gov. ....	C7ZZ 8620 F	7312
Hose - Upper .....		●25305
Hose - Lower .....		●25484

②Two Required ●Flexible Coolant Hose ▲Standard Belt May Also Be Available



Emission DEF Tank Fill, Heater & Coolant Hose Numbers

Emission Control Hose						
I.D./Length	6 ft.	25 ft.	50 ft.	100 ft.	250 ft.	300 ft.
Diesel Emissions Fluid Tank Fill Hose						
3/4	—	DEF750025	—	—	—	DEF750300
1	—	DEF100025	—	—	—	DEF100300

Heater Hose						
I.D./Length	6 ft.	25 ft.	50 ft.	100 ft.	250 ft.	300 ft.
Charter® Straight Heater Hose						
1/2	—	—	28400	—	28403	—
5/8	—	—	28401	—	28404	—
3/4	—	—	28402	—	28405	—
Safety Stripe® Straight Heater Hose						
1/4	—	—	28407	—	—	—
5/16	—	—	28408	—	—	—
3/8	28489	—	28409	—	—	—
1/2	28490	—	28410	—	—	—
5/8	28491	—	28411	—	28417	—
3/4	28492	—	28412	—	28418	—
1	—	28420	28413	—	—	—
Silicone Straight Heater Hose						
3/8	—	26239	—	—	—	—
1/2	—	26240	—	—	—	—
5/8	—	26241	—	—	—	—
3/4	—	26242	—	—	—	—
1	—	26244	—	—	—	—
Green Stripe® Straight Heater Hose						
3/8	—	—	28436	—	—	—
1/2	—	—	28439	—	—	28440
5/8	—	—	28441	—	—	28447
3/4	—	—	28442	—	—	28448
7/8	—	—	28443	—	—	—
1	—	—	28444	—	—	28449
1 1/4	—	—	28445	—	—	—
Heavy Duty Straight Heater Hose (High Pressure)						
1/4	—	—	28435HD	—	—	28452HD (500 FT.)

Coolant Hose						
I.D./Length	3 ft.	I.D./Length	3 ft.	I.D./Length	3 ft.	
500°F Severe Service Straight Silicone Coolant Hose						
1	28225	2	28229	3	28233	—
1 1/4	28226	2 1/4	28230	—	—	—
1 1/2	28227	2 1/2	28231	—	—	—
1 3/4	28228	2 3/4	28232	—	—	—

Size Lists

# STRAIGHT HOSE SIZE LIST



Coolant Hose - Cont.						
I.D./Length	3 ft.	I.D./Length	3 ft.	I.D./Length	3 ft.	
<b>FleetRunner® Hi-Temp Straight Coolant Hose</b>						
7/8	24614	1 1/2	24624	2 1/4	24636	—
1	24616	1 5/8	24626	2 3/8	24638	—
1 1/8	24618	1 3/4	24628	2 1/2	24640	—
1 1/4	21620	1 7/8	24630	2 3/4	24644	—
1 3/8	24622	2	24632	3	24648	—
<b>Vulco® Straight Coolant Hose</b>						
1/2	24008	1 5/8	24026	2 5/8	24042	—
3/4	24012	1 3/4	24028	2 3/4	24044	—
7/8	24014	1 7/8	24030	2 7/8	24046	—
1	24016	2	24032	3	24048	—
1 1/8	24018	2 1/8	24034	3 1/4	24052	—
1 1/4	24020	2 1/4	24036	3 1/2	24056	—
1 3/8	24022	2 3/8	24038	4	24064	—
1 1/2	24024	2 1/2	24040	—	—	—
<b>Silicone Straight Coolant Hose</b>						
1/2	24808	1 1/2	24824	3	24848	—
5/8	24810	1 5/8	24826	3 1/8	24850	—
3/4	24812	1 3/4	24828	3 1/4	24852	—
7/8	24814	2	24832	3 1/2	24856	—
1	24816	2 1/4	24836	3 3/4	24860	—
1 1/8	24818	2 3/8	24838	4	24864	—
1 1/4	24820	2 1/2	24840	4 1/2	24872	—
1 3/8	24822	2 3/4	24844	—	—	—
<b>Green Stripe® 2-Ply Straight Coolant Hose</b>						
3/4	24212	1 7/8	24230	3	24248	—
7/8	24214	2	24232	3 1/8	24250	—
1	24216	2 1/8	24234	3 1/4	24252	—
1 1/8	24218	2 1/4	24236	3 1/2	24256	—
1 1/4	24220	2 3/8	24238	3 3/4	24260	—
1 3/8	24222	2 1/2	24240	4	24264	—
1 1/2	24224	2 5/8	24242	4 1/2	24272	—
1 5/8	24226	2 3/4	24244	—	—	—
1 3/4	24228	2 7/8	24246	—	—	—
<b>Green Stripe® 4-Ply Straight Coolant Hose</b>						
1 3/4	24428	2 1/2	24440	3 1/4	24452	—
1 7/8	24430	2 5/8	24442	3 1/2	24456	—
2	24432	2 3/4	24444	3 5/8	24458	—
2 1/8	24434	2 7/8	24446	3 3/4	24460	—
2 1/4	24436	3	24448	4	24464	—
2 3/8	24438	3 1/8	24450	5	24480	—



# STRAIGHT HOSE SIZE LIST

Coolant Hose - Cont.						
Green Stripe® Wire Inserted Straight Coolant Hose						
I.D./Length	5 ft.	10 ft.	I.D./Length	5 ft.	10 ft.	
1	24916	28316	2 1/4	24936	28336	—
1 1/8	24918		2 3/8	24938	—	—
1 1/4	24920	28320	2 1/2	24940	28340	—
1 3/8	24922		2 5/8	24942	—	—
1 1/2	24924	28324	2 3/4	24944	28344	—
1 5/8	24926	28326	2 7/8	24946	—	—
1 3/4	24928	28328	3	24948	28348	—
1 7/8	24930	28330	3 1/2	24956	28356	—
2	24932	28332	4	24964	—	—
2 1/8	24934	—	5	24980	—	—
	—	—	6	24996	—	—



## Showing Nominal Belt Top Widths and Outside Lengths with Our Corresponding Belt Numbers

Both Truflex® and PoweRated® belts are listed for your convenience. Standard series Truflex® V-Belts are available in four different sizes: the “0000” series, “1000” series, “2000” series and “3000” series V-Belts. The second and third digits in a standard series belt number indicates the outside circumference of the belt, in inches and the fourth digit indicates additional tenths of an inch of belt length, if any.

IMPORTANT: The top width shown is the width obtained by placing a steel tape across the top of the belt. The outside length is determined by placing a steel tape around the outside of the belt. These methods have been used because they are the ones most commonly used by Dealers and Jobbers when measuring a belt.

Length (in.)	Trueflex® Belt No.	PoweRated® Belt No.	Length (in.)	Trueflex® Belt No.	PoweRated® Belt No.	Length (in.)	Trueflex® Belt No.	PoweRated® Belt No.
<b>1/4" (6 mm) Top Width</b>			<b>3/8" (10 mm) Top Width - Cont.</b>			<b>1/2" (13 mm) Top Width - Cont.</b>		
10.....	0100		34 1/4.....	1345		24.....	2240	6824
11.....	0110		35.....	1350	6735	25.....	2250	6825
12.....	0120		36.....	1360	6736	25 1/2.....	2255	
13.....	0130		37.....	1370	6737	26.....	2260	6826
14.....	0140		38.....	1380	6738	27.....	2270	6827
15.....	0150		39.....	1390	6739	27 1/2.....	2275	
16.....	0160		40.....	1400	6740	28.....	2280	6828
17.....	0170		41.....	1410	6741	28 1/2.....	2285	
18.....	0180		41 1/2.....	1415		29.....	2290	6829
19.....	0190		42.....	1420	6742	29 1/2.....	2295	
20.....	0200		43.....	1430	6743	30.....	2300	6830
21.....	0210		44.....	1440	6744	30 1/2.....	2305	
23.....	0230		45.....	1450	6745	31.....	2310	6831
24.....	0240		46.....	1460	6746	31 3/4.....	2318	
25.....	0250		47.....	1470	6747	32.....	2320	6832
26.....	0260		48.....	1480	6748	32 3/4.....	2328	
27.....	0270		49.....	1490	6749	33.....	2330	6833
28.....	0280		50.....	1500	6750	33 1/4.....	2333	
29.....	0290		51.....	1510	6751	33 3/4.....	2338	
31.....	0310		52.....	1520	6752	34.....	2340	6834
34.....	0340		53.....	1530	6753	34 1/2.....	2346	
35.....	0350		54.....	1540	6754	35.....	2350	6835
36.....	0360		55.....	1550	6755	36.....	2360	6836
38.....	0380		56.....	1560	6756	37.....	2370	6837
46.....	0460		57.....	1570	6757	38.....	2380	6838
<b>3/8" (10 mm) Top Width</b>			58.....	1580	6758	39.....	2390	6839
11.....	1110		59.....	1590	6759	40.....	2400	6840
12.....	1120		60.....	1600	6760	40 1/2.....	2405	
13.....	1130		61.....	1610	6761	41.....	2410	6841
14.....	1140		62.....	1620	6762	42.....	2420	6842
15.....	1150		63.....	1630	6763	43.....	2430	6843
16.....	1160	6716	64.....	1640	6764	44.....	2440	6844
17.....	1170	6717	65.....	1650	6765	45.....	2450	6845
18.....	1180	6718	66.....	1660	6766	46.....	2460	6846
19.....	1190	6719	67.....	1670		47.....	2470	6847
20.....	1200	6720	67 1/2.....	1675		47 1/2.....	2475	
21.....	1210	6721	68.....	1680		48.....	2480	6848
22.....	1220	6722	69.....	1690		49.....	2490	6849
23.....	1230	6723	70.....	1700		50.....	2500	6850
24.....	1240	6724	71.....	1710		51.....	2510	6851
24 1/2.....	1245		73.....	1730		52.....	2520	6852
25.....	1250	6725	74.....	1740	6774	53.....	2530	6853
25 1/2.....	1255		<b>1/2" (13 mm) Top Width</b>			54.....	2540	6854
26.....	1260	6726	15.....	2150		55.....	2550	6855
26 1/2.....	1265		16.....	2160		56.....	2560	6856
27.....	1270	6727	17.....	2170	6817	57.....	2570	6857
27 1/2.....	1275		18.....	2180	6818	58.....	2580	6858
28.....	1280	6728	18 3/4.....	2188		59.....	2590	6859
28 1/2.....	1285		19.....	2190	6819	60.....	2600	6860
29.....	1290	6729	20.....	2200	6820	61.....	2610	6861
29 1/4.....	1293		21.....	2210	6821	62.....	2620	6862
30.....	1300	6730	21 1/2.....	2215		63.....	2630	6863
31.....	1310	6731	22.....	2220	6822	64.....	2640	6864
32.....	1320	6732	23.....	2230	6823	65.....	2650	6865
33.....	1330	6733	23 1/2.....	2235		66.....	2660	6866
34.....	1340	6734				67.....	2670	6867
						68.....	2680	6868

Size Lists





TRUFLEX® AND POWERATED® V-BELTS – LISTED BY SIZE

Length (in.)	Trueflex® Belt No.	PowerRated® Belt No.	Length (in.)	Trueflex® Belt No.	PowerRated® Belt No.	Length (in.)	Trueflex® Belt No.	PowerRated® Belt No.
<b>1/2" (13 mm) Top Width - Cont.</b>			<b>21/32" (17 mm) Top Width - Cont.</b>			<b>21/32" (17 mm) Top Width - Cont.</b>		
69.....	2690	6869	25.....	3250	6925	63.....	3630	6963
70.....	2700	6870	26.....	3260	6926	64.....	3640	6964
71.....	2710	6871	26 1/2.....	3265		65.....	3650	6965
72.....	2720	6872	27.....	3270	6927	66.....	3660	6966
73.....	2730	6873	28.....	3280	6928	67.....	3670	6967
74.....	2740	6874	29.....	3290	6929	68.....	3680	6968
75.....	2750	6875	30.....	3300	6930	69.....	3690	6969
76.....	2760	6876	31.....	3310	6931	70.....	3700	6970
77.....	2770	6877	32.....	3320	6932	71.....	3710	6971
78.....	2780	6878	33.....	3330	6933	72.....	3720	6972
79.....	2790	6879	34.....	3340	6934	73.....	3730	6973
80.....	2800	6880	35.....	3350	6935	74.....	3740	6974
81.....	2810	6881	35 1/2.....	3355		75.....	3750	6975
82.....	2820	6882	36.....	3360	6936	76.....	3760	6976
83.....	2830	6883	37.....	3370	6937	77.....	3770	6977
84.....	2840	6884	38.....	3380	6938	78.....	3780	6978
85.....	2850	6885	39.....	3390	6939	79.....	3790	6979
86.....	2860	6886	40.....	3400	6940	80.....	3800	6980
87.....	2870	6887	41.....	3410	6941	81.....	3810	6981
88.....	2880	6888	42.....	3420	6942	82.....	3820	6982
89.....	2890	6889	43.....	3430	6943	83.....	3830	6983
90.....	2900	6890	44.....	3440	6944	84.....	3840	6984
91.....	2910	6891	45.....	3450	6945	85.....	3850	6985
92.....	2920	6892	46.....	3460	6946	86.....	3860	6986
93.....	2930	6893	47.....	3470	6947	87.....	3870	6987
94.....	2940	6894	48.....	3480	6948	88.....	3880	6988
95.....	2950	6895	49.....	3490	6949	89.....	3890	6989
96.....	2960	6896	50.....	3500	6950	90.....	3900	6990
97.....	2970	6897	51.....	3510	6951	91.....	3910	6991
98.....	2980	6898	52.....	3520	6952	92.....	3920	6992
99.....	2990	6899	53.....	3530	6953	93.....	3930	6993
100.....	2999	68100	54.....	3540	6954	94.....	3940	6994
105.....	68105		55.....	3550	6955	95.....	3950	6995
107.....	68107		56.....	3560	6956	96.....	3960	6996
117.....	68117		57.....	3570	6957	97.....	3970	6997
			58.....	3580	6958	98.....	3980	6998
			59.....	3590	6959	99.....	3990	6999
			60.....	3600	6960	100.....	3999	69100
			61.....	3610	6961			
			62.....	3620	6962			
<b>21/32" (17 mm) Top Width</b>								
23.....	3230	6923						
24.....	3240	6924						



Select Belts by Application - Not Size

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Construction
6400BR	86 1/2	2198	1/2	13	WRAPPED	6500BR	40 3/4	1035	3/8	10	WRAPPED
6401BR	89 3/4	2281	1/2	13	WRAPPED	6501BR	74 1/2	1894	1/2	13	WRAPPED
6402BR	74 3/4	1899	21/32	17	WRAPPED	6502BR	67 3/4	1721	21/32	17	WRAPPED
6405BR	44	1119	21/32	17	WRAPPED	6503BR	86 1/2	2199	1/2	13	WRAPPED
6406BR	60 3/4	1543	21/32	17	WRAPPED	6506BR	81 1/4	2064	21/32	17	WRAPPED
6407BR	91 1/8	2315	1/2	13	WRAPPED	6508BR	80 3/4	2052	1/2	13	WRAPPED
6408BR	78	1981	21/32	17	WRAPPED	6509BR	40 1/2	1029	3/8	10	WRAPPED
6409BR	122 1/2	3112	1/2	13	DOUBLE V	6510BR	54 3/4	1391	21/32	17	WRAPPED
6411BR	30 1/2	777	3/8	10	WRAPPED	6511BR	38 1/2	979	21/32	17	WRAPPED
6412BR	84 7/8	2155	1/2	13	WRAPPED	6513BR	80 1/4	2038	3/8	10	WRAPPED
6413BR	32 1/2	825	5/16	8	IND. 60° M SECT	6514BR	41 1/8	1045	21/32	17	WRAPPED
6414BR	78 1/2	1995	1/2	13	WRAPPED	6515BR	81 1/2	2071	21/32	17	RAW EDGE
6415BR	82 1/2	2097	1/2	13	WRAPPED	6517BR	35 1/2	903	1/2	13	WRAPPED
6416BR	100 3/4	2559	21/32	17	WRAPPED	6518BR	85 3/4	2179	1/2	13	WRAPPED
6417BR	76 1/4	1937	1/2	13	WRAPPED	6519BR	78 1/4	1988	1/2	13	WRAPPED
6418BR	88 3/4	2255	1/2	13	WRAPPED	6520BR	71 3/4	1822	21/32	17	WRAPPED
6419BR	55 1/8	1400	21/32	17	WRAPPED	6521BR	93 1/2	2375	1/2	13	WRAPPED
6422BR	46 1/2	1181	1/2	13	WRAPPED	6523BR	80 1/2	2045	1/2	13	WRAPPED
6423BR	45 1/2	1156	21/32	17	COGGED	6524BR	91 1/2	2324	1/2	13	WRAPPED
6424BR	74 1/2	1892	1/2	13	WRAPPED	6525BR	71 3/4	1823	1/2	13	WRAPPED
6425BR	41	1040	1/2	13	WRAPPED	6527BR	67 7/8	1724	21/32	17	WRAPPED
6426BR	33	841	3/8	10	WRAPPED	6528BR	36	914	1/2	13	RAW EDGE
6428BR	105 5/8	2682	1/2	13	WRAPPED	6529BR	46	1168	1/2	13	RAW EDGE
6429BR	44 5/8	1135	21/32	17	COGGED	6530BR	63	1600	1/2	13	RAW EDGE
6431BR	89 5/8	2276	1/2	13	WRAPPED	6532BR	87 3/8	2219	1/2	13	WRAPPED
6432BR	95 1/2	2426	1/2	13	WRAPPED	6533BR	98 3/8	2499	1/2	13	WRAPPED
6433BR	36 1/2	925	3/8	10	COGGED	6534BR	24 3/4	630	3/8	10	WRAPPED
6434BR	82 3/4	2101	1/2	13	WRAPPED	6537BR	86 3/4	2204	21/32	17	WRAPPED
6435BR	26 1/2	673	3/8	10	COGGED	6538BR	33 1/2	851	1 1/4	32	BANDED
6436BR	56 1/2	1435	1 1/4	32	BANDED	6539BR	43 1/8	1095	1 1/4	32	BANDED
6438BR	97 1/2	2476	1/2	13	WRAPPED	6540BR	22 3/4	578	1/2	13	RAW EDGE
6439BR	47 1/2	1208	21/32	17	WRAPPED	6543BR	58 1/2	1487	3/4	19	RIBBED
6440BR	52 1/4	1327	1 1/4	32	BANDED	6544BR	24 1/4	616	1/2	13	COGGED
6441BR	44 1/8	1121	21/32	17	COGGED	6545BR	38 3/8	975	1/2	13	WRAPPED
6444BR	83 5/8	2124	1/2	13	WRAPPED	6546BR	24 3/4	627	1/2	13	RAW EDGE
6446BR	52 1/2	1334	21/32	17	WRAPPED	6547BR	52 3/8	1331	21/32	17	COGGED
6447BR	52 7/8	1343	21/32	17	WRAPPED	6548BR	42 7/8	1089	21/32	17	COGGED
6448BR	67 3/4	1721	1/2	13	WRAPPED	6549BR	46 1/8	1172	21/32	17	COGGED
6449BR	55 1/2	1411	1/2	13	WRAPPED	6550BR	44 5/8	1133	21/32	17	COGGED
6451BR	62 1/2	1588	1/2	13	WRAPPED	6551BR	82 3/8	2092	1/2	13	WRAPPED
6452BR	95 1/2	2427	1/2	13	WRAPPED	6552BR	52 1/4	1327	1/2	13	RAW EDGE
6453BR	30 3/4	782	1/2	13	WRAPPED	6553BR	50 3/4	1288	1/2	13	RAW EDGE
6454BR	82 1/4	2089	21/32	17	WRAPPED	6554BR	35 3/4	906	21/32	17	WRAPPED
6455BR	70 3/8	1787	1/2	13	DOUBLE V	6555BR	78	1981	21/32	17	WRAPPED
6456BR	107 1/2	2730	1/2	13	DOUBLE V	6556BR	41 1/2	1055	21/32	17	WRAPPED
6457BR	92 1/2	2350	1/2	13	WRAPPED	6557BR	38 1/4	983	3/8	10	WRAPPED
6458BR	78 7/8	2003	1/2	13	WRAPPED	6558BR	81 3/8	2067	1/2	13	WRAPPED
6459BR	88 1/2	2248	1/2	13	WRAPPED	6559BR	65 3/8	1661	1/2	13	WRAPPED
6460BR	32 3/8	822	3/8	10	WRAPPED	6562BR	38 1/4	972	1/2	13	WRAPPED
6463BR	88 7/8	2257	1/2	13	WRAPPED	6563BR	50 1/4	1276	21/32	17	WRAPPED
6464BR	64 3/4	1645	21/32	17	WRAPPED	6564BR	55 1/4	1403	21/32	17	WRAPPED
6466BR	45	1141	1 1/4	32	BANDED	6565BR	38 3/4	983	1/2	13	WRAPPED
6467BR	83 5/8	2124	21/32	17	WRAPPED	6566BR	140 1/4	3561	21/32	17	WRAPPED
6469BR	31 1/2	802	3/8	10	WRAPPED	6567BR	145 7/8	3705	21/32	17	WRAPPED
6470BR	51 5/8	1311	1 1/4	32	BANDED	6568BR	129	3274	21/32	17	WRAPPED
6471BR	73 1/4	1861	1/2	13	DOUBLE V	6569BR	169 3/8	4303	21/32	17	WRAPPED
6472BR	44 1/4	1126	21/32	17	COGGED	6570BR	146 5/8	3724	1/2	13	DOUBLE V
6473BR	22 1/4	566	1/2	13	RAW EDGE	6571BR	103 3/4	2637	1/2	13	DOUBLE V
6474BR	89 1/2	2275	1/2	13	WRAPPED	6572BR	79 1/8	2010	1/2	13	WRAPPED
6475BR	47 3/8	1203	1/2	13	WRAPPED	6573BR	82 3/8	2092	21/32	17	WRAPPED
6476BR	87 1/2	2222	1/2	13	WRAPPED	6574BR	121 1/4	3079	21/32	17	WRAPPED
6477BR	99	2515	1/2	13	WRAPPED	6575BR	97 1/4	2470	21/32	17	WRAPPED
6478BR	70 1/4	1784	1/2	13	WRAPPED	6576BR	51 3/4	1315	21/32	17	WRAPPED
6480BR	101 7/8	2586	21/32	17	WRAPPED	6577BR	134 3/8	3414	1/2	13	WRAPPED
6481BR	120 1/8	3053	1/2	13	WRAPPED	6578BR	83 7/8	2130	1/2	13	WRAPPED
6482BR	68 1/4	1730	21/32	17	WRAPPED	6579BR	107 1/4	2723	1/2	13	DOUBLE V
6484BR	126 1/2	3213	1/2	13	WRAPPED	6581BR	61	1549	1/2	13	RAW EDGE
6485BR	133 3/8	3389	21/32	17	WRAPPED	6582BR	91 1/8	2316	1/2	13	RAW EDGE
6486BR	127 5/8	3243	1/2	13	WRAPPED	6583BR	51 1/8	1300	1/2	13	RAW EDGE
6487BR	49 1/2	1257	21/32	17	COGGED	6584BR	105 1/4	2673	21/32	17	RAW EDGE
6488BR	69 1/4	1759	21/32	17	WRAPPED	6586BR	50 1/8	1275	1 1/4	32	BANDED
6490BR	90 3/4	2305	1/2	13	WRAPPED	6588BR	34 1/2	876	3/8	10	RAW EDGE
6491BR	53	1346	1/2	13	WRAPPED	6589BR	123 5/8	3140	21/32	17	WRAPPED
6492BR	109 5/8	2785	21/32	17	WRAPPED	6590BR	54	1372	21/32	17	RAW EDGE
6494BR	35 1/2	902	21/32	17	WRAPPED	6591BR	87 3/4	2229	21/32	17	RAW EDGE
6498BR	54	1372	1/2	13	WRAPPED	6592BR	81 3/4	2077	21/32	17	WRAPPED

Size Lists



# BLADERUNNER® BELTS – LISTED BY NUMBER

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Construction
6593BR	55 7/8	1419	1 3/16	30	BANDED	6682BR	68 5/8	1743	21/32	17	WRAPPED
6596BR	136 5/8	3470	21/32	17	WRAPPED	6683BR	61 1/8	1553	21/32	17	WRAPPED
6597BR	153 5/8	3907	21/32	17	WRAPPED	6684BR	114 1/2	2908	1/2	13	WRAPPED
6598BR	158 1/4	4021	21/32	17	WRAPPED	6685BR	50 1/2	1283	1/2	13	WRAPPED
6599BR	142 1/4	3614	21/32	17	WRAPPED	6686BR	141 3/8	3591	1/2	13	WRAPPED
6601BR	83 1/4	2115	1/2	13	WRAPPED	6687BR	126 7/8	3223	21/32	17	DOUBLE V
6603BR	77	1956	1/2	13	WRAPPED	6688BR	117 1/4	2978	21/32	17	WRAPPED
6604BR	117 5/8	2987	1/2	13	WRAPPED	6689BR	32 1/2	825	3/8	10	COGGED
6605BR	45 1/2	1157	21/32	17	WRAPPED	6690BR	88 7/8	2257	1/2	13	WRAPPED
6606BR	90 1/2	2299	21/32	17	WRAPPED	6691BR	51 1/8	1299	21/32	17	WRAPPED
6608BR	20 1/2	521	3/8	10	WRAPPED	6692BR	148 3/8	3769	21/32	17	WRAPPED
6609BR	28 3/16	716	3/8	10	RAW EDGE	6693BR	225 3/4	5734	21/32	17	WRAPPED
6610BR	29 1/2	749	3/8	10	RAW EDGE	6694BR	112 5/8	2861	21/32	17	DOUBLE V
6611BR	31 1/2	800	1/2	13	RAW EDGE	6695BR	124 1/2	3162	21/32	17	DOUBLE V
6612BR	31 5/8	803	3/8	10	RAW EDGE	6696BR	136 1/2	3467	21/32	17	DOUBLE V
6613BR	30	762	3/8	10	RAW EDGE	6697BR	54 5/8	1387	1/2	13	RAW EDGE
6614BR	89 1/4	2266	21/32	17	WRAPPED	6698BR	56 5/8	1438	1/2	13	RAW EDGE
6615BR	112 3/4	2863	21/32	17	WRAPPED	6699BR	32 1/8	816	1 3/32	28	RIBBED
6616BR	142 1/8	3609	21/32	17	WRAPPED	6700BR	28 5/8	727	15/16	24	RIBBED
6617BR	36 7/8	937	21/32	17	WRAPPED	6701BR	89 3/4	2280	21/32	17	WRAPPED
6618BR	32 1/2	825	21/32	17	WRAPPED	6702BR	85 1/4	2165	21/32	17	WRAPPED
6619BR	36 1/4	921	3/8	10	WRAPPED	6703BR	93 1/4	2369	21/32	17	WRAPPED
6620BR	59 3/4	1518	1/2	13	WRAPPED	6704BR	91 1/4	2318	21/32	17	WRAPPED
6621BR	33 3/8	848	1/2	13	WRAPPED	6705BR	83 1/4	2115	21/32	17	WRAPPED
6622BR	135 3/4	3448	21/32	17	DOUBLE V	6706BR	66 7/8	1699	5/8	16	COGGED
6623BR	30 5/8	778	1/2	13	WRAPPED	6707BR	143 1/2	3645	1/2	13	WRAPPED
6624BR	30 1/2	775	1/2	13	RAW EDGE	6708BR	146 1/8	3712	1/2	13	WRAPPED
6625BR	83	2108	1 1/4	32	BANDED	6709BR	89 1/2	2273	1/2	13	WRAPPED
6626BR	162 1/4	4121	1/2	13	WRAPPED	6710BR	94 3/8	2397	1/2	13	WRAPPED
6627BR	87 7/8	2232	1/2	13	WRAPPED	6711BR	91 1/8	2315	1/2	13	WRAPPED
6628BR	124	3150	1/2	13	RAW EDGE	6712BR	60	1524	1/2	13	WRAPPED
6629BR	80 3/4	2051	1/2	13	DOUBLE V	6713BR	90 3/8	2296	1/2	13	WRAPPED
6630BR	69 7/8	1775	21/32	17	WRAPPED	6714BR	93 1/4	2369	1/2	13	WRAPPED
6633BR	114 1/4	2902	1/2	13	WRAPPED	6715BR	118 3/8	3007	1/2	13	WRAPPED
6635BR	74	1880	1/2	13	DOUBLE V	6716BR	142 3/8	3616	1/2	13	WRAPPED
6636BR	101 7/8	2588	1/2	13	WRAPPED	6717BR	149 7/8	3807	1/2	13	WRAPPED
6637BR	79 1/4	2013	1/2	13	WRAPPED	6718BR	152 1/8	3864	1/2	13	WRAPPED
6638BR	96 3/4	2458	1/2	13	WRAPPED	6719BR	154 3/4	3931	21/32	17	WRAPPED
6639BR	52 1/4	1327	1/2	13	WRAPPED	6720BR	175 1/2	4458	21/32	17	WRAPPED
6640BR	80 1/4	2038	1/2	13	WRAPPED	6721BR	97 1/4	2470	21/32	17	WRAPPED
6641BR	88 1/4	2241	1/2	13	WRAPPED	6722BR	190 3/8	4836	21/32	17	WRAPPED
6642BR	99 1/4	2520	1/2	13	WRAPPED	6723BR	156 3/8	3972	21/32	17	DOUBLE V
6643BR	90 3/4	2305	1/2	13	WRAPPED	6724BR	119 1/4	3029	21/32	17	DOUBLE V
6644BR	76 3/4	1949	21/32	17	WRAPPED	6725BR	128 3/8	3261	21/32	17	DOUBLE V
6645BR	88 7/8	2258	21/32	17	WRAPPED	6726BR	52 5/8	1337	1/2	13	COGGED
6646BR	133 1/8	3381	21/32	17	WRAPPED	6727BR	131 7/8	3350	1/2	13	WRAPPED
6647BR	80 3/8	2041	21/32	17	WRAPPED	6728BR	116 1/8	2950	21/32	17	WRAPPED
6648BR	118 3/8	3006	21/32	17	WRAPPED	6729BR	147 1/2	3747	21/32	17	WRAPPED
6649BR	90 3/8	2294	21/32	17	WRAPPED	6730BR	152 1/4	3867	21/32	17	WRAPPED
6650BR	111 3/8	2828	21/32	17	WRAPPED	6731BR	162 5/8	4131	21/32	17	WRAPPED
6651BR	103 7/8	2637	1/2	13	WRAPPED	6732BR	152	3864	21/32	17	WRAPPED
6652BR	139 1/8	3534	1/2	13	WRAPPED	6733BR	165 5/8	4207	21/32	17	WRAPPED
6653BR	102 1/8	2595	1/2	13	WRAPPED	6734BR	58 7/8	1495	1/2	13	RAW EDGE
6654BR	51 1/4	1302	21/32	17	COGGED	6735BR	59 7/8	1521	1/2	13	RAW EDGE
6655BR	65 1/8	1655	5/8	16	COGGED	6736BR	61 5/8	1565	1/2	13	RAW EDGE
6656BR	44 1/8	1121	1/2	13	WRAPPED	6737BR	79 1/2	2019	1/2	13	RAW EDGE
6657BR	45 1/2	1156	1/2	13	WRAPPED	6738BR	43 7/8	1114	21/32	17	COGGED
6658BR	48 3/8	1228	1/2	13	COGGED	6739BR	79 7/8	2029	21/32	17	COGGED
6659BR	242 3/8	6156	21/32	17	WRAPPED	6740BR	81 3/8	2067	21/32	17	COGGED
6660BR	28 1/2	724	1/2	13	COGGED	6741BR	162 3/4	4134	21/32	17	WRAPPED
6661BR	175 7/8	4468	21/32	17	WRAPPED	6742BR	58 3/4	1492	21/32	17	RIBBED
6662BR	120 5/8	3063	1/2	13	WRAPPED	6743BR	66 3/8	1686	1/2	13	WRAPPED
6663BR	109 3/8	2777	1/2	13	WRAPPED	6744BR	144 3/4	3677	21/32	17	WRAPPED
6664BR	49 1/4	1250	1 1/4	32	BANDED	6745BR	149 7/8	3807	21/32	17	WRAPPED
6665BR	115 3/8	2930	21/32	17	WRAPPED	6746BR	151 1/2	3848	21/32	17	WRAPPED
6666BR	57 7/8	1471	21/32	17	RIBBED	6747BR	168	4267	21/32	17	WRAPPED
6667BR	38	965	3/8	10	COGGED	6748BR	132	3353	21/32	17	DOUBLE V
6668BR	29 1/4	742	9/16	14	RIBBED	6749BR	114 1/4	2902	21/32	17	DOUBLE V
6669BR	47 3/8	1203	9/16	14	RIBBED	6750BR	66 3/8	1686	1/2	13	RAW EDGE
6670BR	41 1/4	1046	1 1/4	32	BANDED	6751BR	80 7/8	2054	21/32	17	RAW EDGE
6671BR	36	914	3/8	10	RAW EDGE	6752BR	119	3023	21/32	17	WRAPPED
6672BR	79 1/4	2013	1/2	13	WRAPPED	6753BR	88	2235	21/32	17	WRAPPED
6673BR	31 5/8	803	3/8	10	COGGED	6754BR	83 5/8	2124	21/32	17	WRAPPED
6674BR	57 1/8	1451	1/2	13	WRAPPED	6755BR	56 3/8	1432	1/2	13	WRAPPED
6675BR	75 3/8	1915	21/32	17	WRAPPED	6756BR	70 3/8	1788	1/2	13	WRAPPED
6676BR	83 1/4	2115	21/32	17	WRAPPED	6757BR	92 3/8	2346	1/2	13	WRAPPED
6677BR	45 1/4	1149	21/32	17	WRAPPED	6758BR	95 3/8	2423	1/2	13	WRAPPED
6678BR	12 1/4	311	1	25	SYNCHRONOUS	6759BR	145	3683	21/32	17	WRAPPED
6679BR	28	711	3/8	10	RAW EDGE	6760BR	163 1/2	4153	21/32	17	WRAPPED
6680BR	35 1/8	892	11/16	18	COGGED	6761BR	183 3/8	4658	21/32	17	WRAPPED
6681BR	79 1/2	2019	1/2	13	WRAPPED	6762BR	173 3/8	4404	7/8	22	WRAPPED

# BLADERUNNER® BELTS – LISTED BY NUMBER



Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Construction
6763BR	110 1/4	2800	1/2	13	WRAPPED	6857BR	102 1/4	2597	21/32	17	WRAPPED
6764BR	92 3/8	2346	1/2	13	WRAPPED	6858BR	106 1/4	2699	21/32	17	WRAPPED
6765BR	98 1/8	2492	1/2	13	WRAPPED	6859BR	162 1/4	4121	21/32	17	WRAPPED
6766BR	144 1/8	3661	1/2	13	WRAPPED	6860BR	186 1/4	4731	21/32	17	WRAPPED
6767BR	147 5/8	3750	21/32	17	WRAPPED	6861BR	69 1/4	1759	1/2	13	RAW EDGE
6768BR	160 1/4	4070	21/32	17	WRAPPED	6862BR	72 5/8	1845	1/2	13	RAW EDGE
6769BR	161 1/4	4096	21/32	17	WRAPPED	6863BR	61 1/8	1553	1/2	13	RAW EDGE
6770BR	172 3/4	4388	21/32	17	WRAPPED	6864BR	53 1/4	1353	21/32	17	WRAPPED
6771BR	211 1/4	5366	21/32	17	WRAPPED	6865BR	62 1/4	1581	21/32	17	WRAPPED
6772BR	64 3/4	1645	1 1/4	32	BANDED	6866BR	84 1/4	2140	21/32	17	WRAPPED
6773BR	78 1/2	1994	5/8	16	SYNCHRONOUS	6867BR	126	3200	5/8	16	WRAPPED
6774BR	77 7/8	1978	1/2	13	WRAPPED	6868BR	166 5/8	4232	5/8	16	WRAPPED
6775BR	85 3/8	2169	1/2	13	WRAPPED	6869BR	179 1/4	4553	5/8	16	WRAPPED
6776BR	96 5/8	2454	1/2	13	WRAPPED	6870BR	204 3/8	5191	5/8	16	WRAPPED
6777BR	122 1/8	3102	1/2	13	WRAPPED	6871BR	58 3/8	1483	1/2	13	WRAPPED
6778BR	134	3404	21/32	17	WRAPPED	6872BR	113 1/4	2877	1/2	13	WRAPPED
6779BR	138 1/4	3512	21/32	17	WRAPPED	6873BR	141 3/8	3591	1/2	13	WRAPPED
6780BR	75 3/8	1915	1/2	13	WRAPPED	6874BR	119 3/8	3032	1/2	13	WRAPPED
6781BR	107 3/8	2727	1/2	13	WRAPPED	6875BR	148 1/8	3762	1/2	13	WRAPPED
6782BR	153 3/4	3905	1/2	13	WRAPPED	6876BR	155 1/4	3943	1/2	13	WRAPPED
6783BR	143 3/8	3642	21/32	17	WRAPPED	6877BR	94 1/4	2394	21/32	17	WRAPPED
6784BR	185 3/4	4718	21/32	17	WRAPPED	6878BR	169 7/8	4315	21/32	17	WRAPPED
6785BR	135 5/8	3445	21/32	17	WRAPPED	6879BR	176 1/8	4474	21/32	17	WRAPPED
6786BR	137 1/2	3493	21/32	17	WRAPPED	6880BR	185 1/4	4705	21/32	17	WRAPPED
6787BR	147 1/8	3737	21/32	17	WRAPPED	6881BR	196 3/8	4988	21/32	17	WRAPPED
6788BR	120 3/4	3067	21/32	17	DOUBLE V	6882BR	201	5105	21/32	17	WRAPPED
6789BR	130 1/2	3315	21/32	17	DOUBLE V	6883BR	203 1/4	5163	21/32	17	WRAPPED
6790BR	56 1/4	1429	21/32	17	COGGED	6884BR	219 5/8	5578	21/32	17	WRAPPED
6791BR	63 1/4	1607	21/32	17	COGGED	6885BR	175	4445	5/8	16	WRAPPED
6792BR	61 3/8	1559	1/2	13	WRAPPED	6886BR	59 1/2	1511	1/2	13	COGGED
6793BR	62 3/8	1584	1/2	13	WRAPPED	6887BR	58 1/4	1480	1/2	13	COGGED
6794BR	52 5/8	1337	1 3/16	30	BANDED	6888BR	64 1/4	1632	1/2	13	COGGED
6795BR	122 7/8	3121	1 1/4	32	BANDED	6889BR	65 7/8	1673	1/2	13	RAW EDGE
6796BR	112 5/8	2861	1 1/4	32	BANDED	6890BR	67	1702	1/2	13	RAW EDGE
6797BR	112 1/4	2851	1 1/4	32	BANDED	6891BR	70 3/4	1797	1/2	13	RAW EDGE
6798BR	83 1/4	2115	1/2	13	WRAPPED	6892BR	155 3/8	3947	21/32	17	WRAPPED
6799BR	61 1/4	1556	1/2	13	WRAPPED	6893BR	174 5/8	4435	21/32	17	WRAPPED
6800BR	147 1/8	3737	21/32	17	WRAPPED	6894BR	34 1/2	876	3/8	10	COGGED
6801BR	165 3/8	4201	21/32	17	WRAPPED	6895BR	46 1/2	1181	3/8	10	COGGED
6802BR	176 3/4	4489	21/32	17	WRAPPED	6896BR	59 1/2	1511	1/2	13	WRAPPED
6803BR	195	4953	21/32	17	WRAPPED	6897BR	159 7/8	4061	1/2	13	WRAPPED
6804BR	145 5/8	3699	21/32	17	WRAPPED	6898BR	181 7/8	4620	1/2	13	WRAPPED
6805BR	107 5/8	2734	21/32	17	WRAPPED	6899BR	73 1/4	1861	1/2	13	RAW EDGE
6806BR	95 5/8	2429	21/32	17	WRAPPED	6900BR	113 5/8	2886	1/2	13	RAW EDGE
6807BR	68 3/4	1746	1/2	13	RAW EDGE	6901BR	127 1/4	3232	21/32	17	WRAPPED
6808BR	34	864	1 1/4	32	BANDED	6902BR	182 3/4	4642	21/32	17	WRAPPED
6809BR	51 3/8	1305	1/2	13	WRAPPED	6903BR	39 7/8	1013	1 5/32	29	BANDED
6810BR	105 3/8	2677	1/2	13	WRAPPED	6904BR	103 3/8	2626	21/32	17	WRAPPED
6811BR	84 1/4	2140	1/2	13	WRAPPED	6905BR	125 1/2	3188	21/32	17	WRAPPED
6812BR	83 1/4	2115	21/32	17	WRAPPED	6906BR	141	3581	21/32	17	WRAPPED
6813BR	45 1/4	1149	1 1/4	32	BANDED	6907BR	51 7/8	1318	1/2	13	COGGED
6814BR	87 1/4	2216	21/32	17	WRAPPED	6908BR	80 3/4	2051	1/2	13	COGGED
6815BR	80 1/4	2038	21/32	17	WRAPPED	6909BR	50 1/8	1273	21/32	17	COGGED
6816BR	93 1/4	2369	21/32	17	WRAPPED	6910BR	54 3/4	1391	21/32	17	COGGED
6817BR	124 1/4	3156	21/32	17	WRAPPED	6911BR	65 1/8	1654	21/32	17	COGGED
6818BR	64 3/8	1635	1/2	13	RAW EDGE	6913BR	77 1/4	1962	21/32	17	COGGED
6819BR	53	1346	1/2	13	WRAPPED	6914BR	73 3/4	1873	1/2	13	RAW EDGE
6820BR	55 3/8	1407	1/2	13	WRAPPED	6915BR	59 1/2	1511	1/2	13	RAW EDGE
6821BR	105 7/8	2689	1/2	13	WRAPPED	6916BR	114 1/8	2899	21/32	17	WRAPPED
6822BR	52 1/4	1327	21/32	17	WRAPPED	6917BR	103 7/8	2638	21/32	17	WRAPPED
6823BR	57 1/4	1454	21/32	17	WRAPPED	6918BR	122 3/8	3108	21/32	17	WRAPPED
6837BR	64 1/4	1632	21/32	17	WRAPPED	6919BR	178 3/8	4531	21/32	17	WRAPPED
6838BR	70 1/4	1784	21/32	17	WRAPPED	6920BR	191 3/8	4861	21/32	17	WRAPPED
6839BR	88 1/4	2242	21/32	17	WRAPPED	6921BR	202	5131	21/32	17	WRAPPED
6840BR	78 1/4	1988	21/32	17	WRAPPED	6922BR	49 3/8	1254	1/2	13	WRAPPED
6841BR	30 1/8	765	9/16	14	RIBBED	6923BR	117 3/8	2981	1/2	13	WRAPPED
6842BR	134 3/8	3413	1/2	13	WRAPPED	6924BR	79 3/4	2026	1/2	13	WRAPPED
6843BR	120 1/4	3054	21/32	17	WRAPPED	6925BR	69	1753	1/2	13	DOUBLE V
6844BR	180 1/4	4578	21/32	17	WRAPPED	6926BR	39 3/8	1000	1/2	13	COGGED
6845BR	135	3429	21/32	17	WRAPPED	6927BR	48	1219	1/2	13	RAW EDGE
6846BR	69 1/2	1765	21/32	17	COGGED	6928BR	112 3/8	2854	1/2	13	WRAPPED
6847BR	63 1/2	1613	1/2	13	WRAPPED	6929BR	32 1/8	816	27/32	21	RIBBED
6848BR	115 3/4	2940	1/2	13	WRAPPED	6930BR	46 1/2	1181	21/32	17	RIBBED
6849BR	123 1/4	3131	1/2	13	WRAPPED	6931BR	55 1/8	1400	21/32	17	RIBBED
6850BR	199	5055	5/8	16	WRAPPED	6932BR	69 1/4	1759	21/32	17	RIBBED
6851BR	219 1/4	5575	5/8	16	WRAPPED	6933BR	157 1/4	3994	21/32	17	WRAPPED
6852BR	44 1/8	1121	21/32	17	RAW EDGE	6934BR	198 3/8	5039	21/32	17	WRAPPED
6853BR	165	4191	21/32	17	WRAPPED	6935BR	208 3/8	5293	21/32	17	WRAPPED
6854BR	61 1/4	1556	21/32	17	WRAPPED	6936BR	163 1/2	4153	5/8	16	WRAPPED
6855BR	66 1/4	1683	21/32	17	WRAPPED	6937BR	173	4394	5/8	16	WRAPPED
6856BR	96 1/4	2445	21/32	17	WRAPPED	6938BR	176	4470	5/8	16	WRAPPED

② Set of Two Belts





## BLADERUNNER® BELTS – LISTED BY NUMBER

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Construction
6939BR	36 1/2	927	1/2	13	COGGED	7020BR	71	1803	11/16	18	RIBBED
6940BR	37 1/4	946	1/2	13	COGGED	7021BR	35 3/8	899	13/32	11	RIBBED
6941BR	66 3/4	1695	1/2	13	DOUBLE V	7022BR	42 7/8	1089	1/2	13	RAW EDGE
6942BR	135 1/2	3442	21/32	17	DOUBLE V	7023BR	72 1/4	1835	1 1/4	32	BANDED
6943BR	64 1/2	1638	1/2	13	WRAPPED	7024BR	86 3/4	2203	1/2	13	COGGED
6944BR	98 1/2	2502	1/2	13	WRAPPED	7025BR	39 3/4	1010	1/2	13	RAW EDGE
6945BR	121 1/2	3086	1/2	13	WRAPPED	7026BR	47 1/2	1207	1/2	13	RAW EDGE
6946BR	131 1/2	3340	21/32	17	WRAPPED	7027BR	51 1/4	1302	1/2	13	RAW EDGE
6947BR	219	5563	21/32	17	WRAPPED	7028BR	96 3/8	2448	1/2	13	WRAPPED
6948BR	41 1/8	1045	1/2	13	RAW EDGE	7029BR	110 3/4	2813	1/2	13	WRAPPED
6949BR	99	2515	21/32	17	WRAPPED	7030BR	71 1/4	1810	21/32	17	RAW EDGE
6950BR	168 1/4	4274	21/32	17	WRAPPED	7031BR	179 1/4	4553	21/32	17	WRAPPED
6951BR	91	2311	21/32	21	BANDED	7032BR	177 3/4	4515	21/32	17	WRAPPED
6952BR	57 7/8	1470	1 7/32	31	BANDED	7033BR	193 1/2	4915	21/32	17	WRAPPED
6953BR	58 7/8	1495	1 7/32	31	BANDED	7034BR	170	4318	5/8	16	WRAPPED
6954BR	69 1/8	1757	1 7/32	31	BANDED	7035BR	50	1270	11/16	18	RIBBED
6955BR	68	1727	1 5/8	41	BANDED	7036BR	44 1/2	1130	1/2	13	WRAPPED
6956BR	69	1752	1 5/8	41	BANDED	7037BR	45 3/8	1153	1/2	13	WRAPPED
6957BR	70	1778	1 5/8	41	BANDED	7038BR	60 1/2	1537	1/2	13	WRAPPED
6958BR	71	1803	1 5/8	41	BANDED	7039BR	164	4166	1/2	13	WRAPPED
6959BR	56 3/8	1432	1 7/32	31	BANDED	7040BR	56 1/4	1429	21/32	17	WRAPPED
6960BR	59 3/8	1508	1 7/32	31	BANDED	7041BR	114 5/8	2911	21/32	17	WRAPPED
6961BR	64	1626	1 7/32	31	BANDED	7042BR	189 3/8	4810	21/32	17	WRAPPED
6962BR	65 5/8	1668	1 5/8	41	BANDED	7043BR	237 5/8	6036	21/32	17	WRAPPED
6963BR	69	1753	2 1/32	52	BANDED	7045BR	69 3/8	1762	1/2	13	COGGED
6964BR	77 7/8	1978	2 1/32	52	BANDED	7046BR	73	1854	1/2	13	COGGED
6965BR	44 5/8	1133	15/16	24	RIBBED	7047BR	32 5/8	829	13/32	11	RIBBED
6966BR	47 5/8	1210	15/16	24	RIBBED	7048BR	121 1/4	3080	21/32	17	WRAPPED
6967BR	47 1/4	1200	21/32	21	RIBBED	7049BR	167	4242	21/32	17	WRAPPED
6968BR	57 3/4	1467	7/8	22	COGGED	7050BR	35 1/2	902	21/32	17	WRAPPED
6969BR	83 1/2	2121	21/32	17	RAW EDGE	7051BR	41	1041	21/32	17	WRAPPED
6970BR	180 7/8	4594	21/32	17	WRAPPED	7052BR	47 1/2	1207	1/2	13	WRAPPED
6971BR	204 5/8	5198	21/32	17	WRAPPED	7053BR	108 5/8	2759	1/2	13	WRAPPED
6972BR	235 1/2	5982	21/32	17	WRAPPED	7054BR	140 3/8	3566	1/2	13	WRAPPED
6973BR	35 1/4	895	1/2	13	COGGED	7055BR	109	2769	1/2	13	WRAPPED
6974BR	36 1/8	943	1/2	13	WRAPPED	7056BR	68	1727	21/32	17	COGGED
6975BR	43 5/8	1108	1/2	13	WRAPPED	7057BR	144	3658	21/32	17	WRAPPED
6976BR	72 3/8	1838	1/2	13	WRAPPED	7058BR	159 5/8	4054	21/32	17	WRAPPED
6977BR	125 3/8	3185	1/2	13	WRAPPED	7059BR	264 1/2	6718	21/32	17	WRAPPED
6978BR	136 1/4	3486	1/2	13	WRAPPED	7060BR	92 3/8	2346	21/32	17	DOUBLE V
6979BR	163 1/8	4143	1/2	13	WRAPPED	7061BR	100 1/2	2553	21/32	17	DOUBLE V
6980BR	113 3/4	2889	21/32	17	WRAPPED	7062BR	118 1/4	3004	21/32	17	DOUBLE V
6981BR	119 3/4	3042	21/32	17	WRAPPED	7063BR	123 3/4	3143	21/32	17	DOUBLE V
6982BR	136 3/8	3464	21/32	17	WRAPPED	7064BR	133 1/4	3385	21/32	17	DOUBLE V
6983BR	153 7/8	3908	21/32	17	WRAPPED	7065BR	150	3810	21/32	17	DOUBLE V
6984BR	47 1/2	1207	29/32	23	WRAPPED	7066BR	72 1/2	1842	21/32	17	COGGED
6985BR	49 1/8	1248	1/2	13	COGGED	7067BR	53 1/2	1359	1/2	13	DOUBLE V
6986BR	62 1/4	1581	1/2	13	COGGED	7068BR	86 1/4	2191	21/32	17	WRAPPED
6987BR	161 1/4	4096	1/2	13	WRAPPED	7069BR	149 1/2	3797	21/32	17	WRAPPED
6988BR	174	4420	1/2	13	WRAPPED	7070BR	152 3/4	3880	21/32	17	WRAPPED
6989BR	40 1/4	1022	21/32	17	COGGED	7071BR	136 1/8	3458	1/2	13	WRAPPED
6990BR	42 1/4	1073	21/32	17	COGGED	7072BR	91 1/4	2318	21/32	17	WRAPPED
6991BR	95	2413	21/32	17	RAW EDGE	7073BR	56 7/8	1445	1/2	13	RAW EDGE
6992BR	130 3/8	3312	21/32	17	WRAPPED	7074BR	57 7/8	1464	1/2	13	RAW EDGE
6993BR	51 1/2	1308	21/32	17	RAW EDGE	7076BR	97 5/8	2480	1/2	13	WRAPPED
6994BR	104 7/8	2664	21/32	17	WRAPPED	7077BR	109	2769	21/32	17	DOUBLE V
6995BR	52 1/8	1324	21/32	17	COGGED	7078BR	112	2845	21/32	17	DOUBLE V
6996BR	65 1/4	1657	21/32	17	WRAPPED	7079BR	122 3/4	3118	21/32	17	DOUBLE V
6997BR	156 1/4	3969	21/32	17	WRAPPED	7080BR	76 1/2	1943	1/2	13	WRAPPED
6998BR	139 5/8	3546	5/8	16	WRAPPED	7081BR	65 3/4	1670	21/32	17	COGGED
6999BR	148	3759	5/8	16	WRAPPED	7082BR	155 3/4	3956	5/8	16	WRAPPED
7000BR	163	4140	5/8	16	WRAPPED	7083BR	161 7/8	4112	5/8	16	WRAPPED
7001BR	170 7/8	4340	5/8	16	WRAPPED	7084BR	202 3/4	5150	5/8	16	WRAPPED
7002BR	201	5105	5/8	16	WRAPPED	7085BR	203 1/2	5169	5/8	16	WRAPPED
7003BR	31	787	3/8	10	COGGED	7086BR	182	4623	5/8	16	WRAPPED
7004BR	40 3/8	1026	1/2	13	COGGED	7087BR	79 5/8	2022	15/16	24	RIBBED
7005BR	56 5/8	1438	1/2	13	COGGED	7088BR	57 1/4	1454	1 21/32	42	RIBBED
7006BR	76 3/8	1940	1/2	13	COGGED	7089BR	130 5/8	3318	1/2	13	WRAPPED
7007BR	75 1/8	1908	1/2	13	COGGED	7090BR	131 1/8	3331	1/2	13	WRAPPED
7008BR	37 7/8	962	1/2	13	RAW EDGE	7091BR	66 5/8	1692	1/2	13	COGGED
7009BR	39 1/4	997	1/2	13	RAW EDGE	7092BR	110 3/4	2813	21/32	17	WRAPPED
7010BR	40 1/4	1022	1/2	13	RAW EDGE	7093BR	150 3/4	3829	21/32	17	WRAPPED
7011BR	49	1245	1/2	13	RAW EDGE	7094BR	93 1/4	2369	21/32	17	DOUBLE V
7012BR	49 7/8	1267	1/2	13	RAW EDGE	7095BR	115 1/2	2934	21/32	17	DOUBLE V
7013BR	68 1/4	1734	1/2	13	RAW EDGE	7096BR	129 1/4	3283	21/32	17	DOUBLE V
7014BR	100	2540	1/2	13	WRAPPED	7097BR	60 3/8	1534	1/2	13	RAW EDGE
7015BR	101 1/4	2572	1/2	13	WRAPPED	7098BR	145 1/8	3686	1/2	13	WRAPPED
7016BR	144 5/8	3673	1/2	13	WRAPPED	7099BR	71 1/2	1816	1/2	13	WRAPPED
7017BR	151 1/4	3842	1/2	13	WRAPPED	7100BR	128 1/2	3264	1/2	13	WRAPPED
7018BR	58 7/8	1495	1 1/4	32	BANDED	7101BR	71 1/4	1810	21/32	17	WRAPPED
7019BR	47 5/8	1210	21/32	17	COGGED	7102BR	104 3/8	2651	1 1/4	32	BANDED

② Set of Two Belts



# BLADERUNNER® BELTS – LISTED BY NUMBER



Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Construction
7103BR	119 3/8	3032	1 1/4	32	BANDED	7119BR	146 1/4	3715	1/2	13	WRAPPED
7104BR	136 3/8	3464	1 1/4	32	BANDED	7120BR	116 1/4	2953	1/2	13	DOUBLE V
7105BR	137	3480	1/2	13	WRAPPED	7121BR	114 3/4	2915	21/32	17	DOUBLE V
7106BR	63 1/4	1607	21/32	17	WRAPPED	7122BR	34 5/8	880	13/16	21	BANDED
7107BR	146	3708	5/8	16	WRAPPED	7123BR	41 1/4	1048	13/16	21	BANDED
7108BR	149	3785	5/8	16	WRAPPED	7124BR	49 7/8	1267	1 3/16	30	BANDED
7109BR	151	3835	5/8	16	WRAPPED	7125BR	55 23/32	1415	1 3/16	30	BANDED
7110BR	157	3988	5/8	16	WRAPPED	7126BR	55 23/32	1415	1 3/16	30	BANDED
7111BR	194 1/4	4934	5/8	16	WRAPPED	7127BR	35 1/2	900	9/16	14	RIBBED
7112BR	147	3734	5/8	16	WRAPPED	7128BR	67 1/2	1713	11/16	17	RIBBED
7113BR	154	3912	5/8	16	WRAPPED	7129BR	173 3/4	4413	11/16	18	WRAPPED
7114BR	76	1930	21/32	17	COGGED	7130BR	50 15/16	1294	15/32	12	COGGED
7116BR	175 3/4	4464	7/8	22	WRAPPED	7131BR	58 21/32	1490	15/32	12	COGGED
7117BR	132 3/8	3362	1/2	13	WRAPPED	7132BR	64 23/32	1644	1/2	13	COGGED
7118BR	145 5/8	3699	1/2	13	WRAPPED	7133BR	65 1/16	1652	19/32	15	RAW EDGE



Select Belts By Application - Not size

Length (in.)	Length (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Construction	Belt Number
<b>5/16" (8 mm) Top Width</b>				<b>1/2" (13 mm) Top Width - Cont.</b>				<b>1/2" (13 mm) Top Width - Cont.</b>			
32 1/2	825	IND. 60° M SECT.....	6413BR	45 3/8	1153	WRAPPED.....	7037BR	69 3/8	1762	COGGED.....	7045BR
<b>3/8" (10 mm) Top Width</b>				45 1/2	1156	WRAPPED.....	6657BR	70 1/4	1784	WRAPPED.....	6478BR
20 1/2	521	WRAPPED.....	6608BR	46	1168	RAW EDGE.....	6529BR	70 3/8	1787	DOUBLE V.....	6455BR
24 3/4	630	WRAPPED.....	6534BR	46 1/2	1181	WRAPPED.....	6422BR	70 3/8	1788	WRAPPED.....	6756BR
26 1/2	673	COGGED.....	6435BR	47 3/8	1203	WRAPPED.....	6475BR	70 3/4	1797	RAW EDGE.....	6891BR
28	711	RAW EDGE.....	6679BR	47 1/2	1207	RAW EDGE.....	7026BR	71 1/2	1816	WRAPPED.....	7099BR
28 3/16	716	RAW EDGE.....	6609BR	47 1/2	1207	WRAPPED.....	7052BR	71 3/4	1823	WRAPPED.....	6525BR
29 1/2	749	RAW EDGE.....	6610BR	48	1219	RAW EDGE.....	6927BR	72 3/8	1838	WRAPPED.....	6976BR
30	762	RAW EDGE.....	6613BR	48 3/8	1228	COGGED.....	6658BR	72 5/8	1845	RAW EDGE.....	6862BR
30 1/2	777	WRAPPED.....	6411BR	49	1245	RAW EDGE.....	7011BR	73	1854	COGGED.....	7046BR
31	787	COGGED.....	7003BR	49 1/8	1248	COGGED.....	6985BR	73 1/4	1861	DOUBLE V.....	6471BR
31 1/2	802	WRAPPED.....	6469BR	49 3/8	1254	WRAPPED.....	6922BR	73 1/4	1861	RAW EDGE.....	6899BR
31 5/8	803	RAW EDGE.....	6612BR	49 7/8	1267	RAW EDGE.....	7012BR	73 3/4	1873	RAW EDGE.....	6914BR
31 5/8	803	COGGED.....	6673BR	50 1/2	1283	WRAPPED.....	6685BR	74	1880	DOUBLE V.....	6635BR
32 3/8	822	WRAPPED.....	6460BR	50 3/4	1288	RAW EDGE.....	6553BR	74 1/2	1892	WRAPPED.....	6424BR
32 1/2	825	COGGED.....	6689BR	51 1/8	1300	RAW EDGE.....	6583BR	74 1/2	1894	WRAPPED.....	6501BR
33	841	WRAPPED.....	6426BR	51 1/4	1302	RAW EDGE.....	7027BR	75 1/8	1908	COGGED.....	7007BR
34 1/2	876	RAW EDGE.....	6588BR	51 3/8	1305	WRAPPED.....	6809BR	75 3/8	1915	WRAPPED.....	6780BR
34 1/2	876	COGGED.....	6894BR	51 7/8	1318	COGGED.....	6907BR	76 1/4	1937	WRAPPED.....	6417BR
36	914	RAW EDGE.....	6671BR	52 1/4	1327	RAW EDGE.....	6552BR	76 3/8	1940	COGGED.....	7006BR
36 1/4	921	WRAPPED.....	6619BR	52 1/4	1327	WRAPPED.....	6639BR	76 1/2	1943	WRAPPED.....	7080BR
36 1/2	925	COGGED.....	6433BR	52 5/8	1337	COGGED.....	6726BR	77	1956	WRAPPED.....	6603BR
38	965	COGGED.....	6667BR	53	1346	WRAPPED.....	6491BR	77 7/8	1978	WRAPPED.....	6774BR
38 1/4	983	WRAPPED.....	6557BR	53	1346	WRAPPED.....	6819BR	78 1/4	1988	WRAPPED.....	6519BR
40 1/2	1029	WRAPPED.....	6509BR	53 1/2	1359	DOUBLE V.....	7067BR	78 1/2	1995	WRAPPED.....	6414BR
40 3/4	1035	WRAPPED.....	6500BR	54	1372	WRAPPED.....	6498BR	78 7/8	2003	WRAPPED.....	6458BR
46 1/2	1181	COGGED.....	6895BR	54 5/8	1387	RAW EDGE.....	6697BR	79 1/8	2010	WRAPPED.....	6572BR
80 1/4	2038	WRAPPED.....	6513BR	55 3/8	1407	WRAPPED.....	6820BR	79 1/4	2013	WRAPPED.....	6637BR
<b>13/32" (11 mm) Top Width</b>				55 1/2	1411	WRAPPED.....	6449BR	79 1/4	2013	WRAPPED.....	6672BR
32 5/8	829	RIBBED.....	7047BR	56 3/8	1432	WRAPPED.....	6755BR	79 1/2	2019	WRAPPED.....	6681BR
35 3/8	899	RIBBED.....	7021BR	56 5/8	1438	RAW EDGE.....	6698BR	79 1/2	2019	RAW EDGE.....	6737BR
<b>15/32" (12 mm) Top Width</b>				56 5/8	1438	COGGED.....	7005BR	79 3/4	2026	WRAPPED.....	6924BR
50 15/16	1294	COGGED.....	7130BR	56 7/8	1445	RAW EDGE.....	7073BR	80 1/4	2038	WRAPPED.....	6640BR
58 21/32	1490	COGGED.....	7131BR	57 1/8	1451	WRAPPED.....	6674BR	80 1/2	2045	WRAPPED.....	6523BR
<b>1/2" (13 mm) Top Width</b>				57 7/8	1464	RAW EDGE.....	7074BR	80 3/4	2052	WRAPPED.....	6508BR
22 1/4	566	RAW EDGE.....	6473BR	58 1/4	1480	COGGED.....	6887BR	80 3/4	2051	DOUBLE V.....	6629BR
22 3/4	578	RAW EDGE.....	6540BR	58 3/8	1483	WRAPPED.....	6871BR	80 3/4	2051	COGGED.....	6908BR
24 1/4	616	COGGED.....	6544BR	58 7/8	1495	RAW EDGE.....	6734BR	81 3/8	2067	WRAPPED.....	6558BR
24 3/4	627	RAW EDGE.....	6546BR	59 1/2	1511	COGGED.....	6886BR	82 3/8	2092	WRAPPED.....	6551BR
28 1/2	724	COGGED.....	6660BR	59 1/2	1511	WRAPPED.....	6896BR	82 1/2	2097	WRAPPED.....	6415BR
30 1/2	775	RAW EDGE.....	6624BR	59 1/2	1511	RAW EDGE.....	6915BR	82 3/4	2101	WRAPPED.....	6434BR
30 5/8	778	WRAPPED.....	6623BR	59 3/4	1518	WRAPPED.....	6620BR	83 1/4	2115	WRAPPED.....	6601BR
30 3/4	782	WRAPPED.....	6453BR	59 7/8	1521	RAW EDGE.....	6735BR	83 1/4	2115	WRAPPED.....	6798BR
31 1/2	800	RAW EDGE.....	6611BR	60	1524	WRAPPED.....	6712BR	83 5/8	2124	WRAPPED.....	6444BR
33 3/8	848	WRAPPED.....	6621BR	60 3/8	1534	RAW EDGE.....	7097BR	83 7/8	2130	WRAPPED.....	6578BR
35 1/4	895	COGGED.....	6973BR	60 1/2	1537	WRAPPED.....	7038BR	84 1/4	2140	WRAPPED.....	6811BR
35 1/2	903	WRAPPED.....	6517BR	61	1549	RAW EDGE.....	6581BR	84 7/8	2155	WRAPPED.....	6412BR
36	914	RAW EDGE.....	6528BR	61 1/8	1553	RAW EDGE.....	6863BR	85 3/8	2169	WRAPPED.....	6775BR
36 1/8	943	WRAPPED.....	6974BR	61 1/4	1556	WRAPPED.....	6799BR	85 3/4	2179	WRAPPED.....	6518BR
36 1/2	927	COGGED.....	6939BR	61 3/8	1559	WRAPPED.....	6792BR	86 1/2	2198	WRAPPED.....	6400BR
37 1/4	946	COGGED.....	6940BR	61 5/8	1565	RAW EDGE.....	6736BR	86 1/2	2199	WRAPPED.....	6503BR
37 7/8	962	RAW EDGE.....	7008BR	62 1/4	1581	COGGED.....	6986BR	86 3/4	2203	COGGED.....	7024BR
38 1/4	972	WRAPPED.....	6562BR	62 3/8	1584	WRAPPED.....	6793BR	87 3/8	2219	WRAPPED.....	6532BR
38 3/8	975	WRAPPED.....	6545BR	62 1/2	1588	WRAPPED.....	6451BR	87 1/2	2222	WRAPPED.....	6476BR
38 3/4	983	WRAPPED.....	6565BR	63	1600	RAW EDGE.....	6530BR	87 7/8	2232	WRAPPED.....	6627BR
39 1/4	997	RAW EDGE.....	7009BR	63 1/2	1613	WRAPPED.....	6847BR	88 1/4	2241	WRAPPED.....	6641BR
39 3/8	1000	COGGED.....	6926BR	64 1/4	1632	COGGED.....	6888BR	88 1/2	2248	WRAPPED.....	6459BR
39 3/4	1010	RAW EDGE.....	7025BR	64 3/8	1635	RAW EDGE.....	6818BR	88 3/4	2255	WRAPPED.....	6418BR
40 1/4	1022	RAW EDGE.....	7010BR	64 1/2	1638	WRAPPED.....	6943BR	88 7/8	2257	WRAPPED.....	6463BR
40 3/8	1026	COGGED.....	7004BR	64 23/32	1644	COGGED.....	7132BR	88 7/8	2257	WRAPPED.....	6690BR
41	1040	WRAPPED.....	6425BR	65 3/8	1661	WRAPPED.....	6559BR	89 1/2	2275	WRAPPED.....	6474BR
41 1/8	1045	RAW EDGE.....	6948BR	65 7/8	1673	RAW EDGE.....	6889BR	89 1/2	2273	WRAPPED.....	6709BR
42 7/8	1089	RAW EDGE.....	7022BR	66 3/8	1686	WRAPPED.....	6743BR	89 5/8	2276	WRAPPED.....	6431BR
43 5/8	1108	WRAPPED.....	6975BR	66 3/8	1686	RAW EDGE.....	6750BR	89 3/4	2281	WRAPPED.....	6401BR
44 1/8	1121	WRAPPED.....	6656BR	66 5/8	1692	COGGED.....	7091BR	90 3/8	2296	WRAPPED.....	6713BR
44 1/2	1130	WRAPPED.....	7036BR	66 3/4	1695	DOUBLE V.....	6941BR	90 3/4	2305	WRAPPED.....	6490BR
				67	1702	RAW EDGE.....	6890BR	90 3/4	2305	WRAPPED.....	6643BR
				67 3/4	1721	WRAPPED.....	6448BR	91 1/8	2315	WRAPPED.....	6407BR
				68 1/4	1734	RAW EDGE.....	7013BR	91 1/8	2316	RAW EDGE.....	6582BR
				68 3/4	1746	RAW EDGE.....	6807BR	91 1/8	2315	WRAPPED.....	6711BR
				69	1753	DOUBLE V.....	6925BR	91 1/2	2324	WRAPPED.....	6524BR
				69 1/4	1759	RAW EDGE.....	6861BR	92 3/8	2346	WRAPPED.....	6757BR

② Set of Two Belts



Length (in.)	Length (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Construction	Belt Number
<b>1/2" (13 mm) Top Width - Cont.</b>				<b>1/2" (13 mm) Top Width - Cont.</b>				<b>21/32" (17 mm) Top Width - Cont.</b>			
92 3/8	2346	WRAPPED	6764BR	146 1/4	3715	WRAPPED	7119BR	44 1/8	1121	COGGED	6441BR
92 1/2	2350	WRAPPED	6457BR	146 5/8	3724	DOUBLE V	6570BR	44 1/8	1121	RAW EDGE	6852BR
93 1/4	2369	WRAPPED	6714BR	148 1/8	3762	WRAPPED	6875BR	44 1/4	1126	COGGED	6472BR
93 1/2	2375	WRAPPED	6521BR	149 7/8	3807	WRAPPED	6717BR	44 5/8	1135	COGGED	6429BR
94 3/8	2397	WRAPPED	6710BR	151 1/4	3842	WRAPPED	7017BR	44 5/8	1133	COGGED	6550BR
95 3/8	2423	WRAPPED	6758BR	152 1/8	3864	WRAPPED	6718BR	45 1/4	1149	WRAPPED	6677BR
95 1/2	2426	WRAPPED	6432BR	153 3/4	3905	WRAPPED	6782BR	45 1/2	1156	COGGED	6423BR
95 1/2	2427	WRAPPED	6452BR	155 1/4	3943	WRAPPED	6876BR	45 1/2	1157	WRAPPED	6605BR
96 3/8	2448	WRAPPED	7028BR	159 7/8	4061	WRAPPED	6897BR	46 1/8	1172	COGGED	6549BR
96 5/8	2454	WRAPPED	6776BR	161 1/4	4096	WRAPPED	6987BR	46 1/2	1181	RIBBED	6930BR
96 3/4	2458	WRAPPED	6638BR	162 1/4	4121	WRAPPED	6626BR	47 1/2	1208	WRAPPED	6439BR
97 1/2	2476	WRAPPED	6438BR	163 1/8	4143	WRAPPED	6979BR	47 5/8	1210	COGGED	7019BR
97 5/8	2480	WRAPPED	7076BR	164	4166	WRAPPED	7039BR	49 1/2	1257	COGGED	6487BR
98 1/8	2492	WRAPPED	6765BR	174	4420	WRAPPED	6988BR	50 1/8	1273	COGGED	6909BR
98 3/8	2499	WRAPPED	6533BR	181 7/8	4620	WRAPPED	6898BR	50 1/4	1276	WRAPPED	6563BR
98 1/2	2502	WRAPPED	6944BR	<b>9/16" (14 mm) Top Width</b>				51 1/8	1299	WRAPPED	6691BR
99	2515	WRAPPED	6477BR	29 1/4	742	RIBBED	6668BR	51 1/4	1302	COGGED	6654BR
99 1/4	2520	WRAPPED	6642BR	30 1/8	765	RIBBED	6841BR	51 1/2	1308	RAW EDGE	6993BR
100	2540	WRAPPED	7014BR	35 1/2	900	RIBBED	7127BR	51 3/4	1315	WRAPPED	6576BR
101 1/4	2572	WRAPPED	7015BR	47 3/8	1203	RIBBED	6669BR	52 1/8	1324	COGGED	6995BR
101 7/8	2588	WRAPPED	6636BR	<b>19/32" (15 mm) Top Width</b>				52 1/4	1327	WRAPPED	6822BR
102 1/8	2595	WRAPPED	6653BR	65 1/16	1652	RAW EDGE	7133BR	52 3/8	1331	COGGED	6547BR
103 3/4	2637	DOUBLE V	6571BR	<b>5/8" (16 mm) Top Width</b>				52 1/2	1334	WRAPPED	6446BR
103 7/8	2637	WRAPPED	6651BR	65 1/8	1655	COGGED	6655BR	52 7/8	1343	WRAPPED	6447BR
105 3/8	2677	WRAPPED	6810BR	66 7/8	1699	COGGED	6706BR	53 1/4	1353	WRAPPED	6864BR
105 5/8	2682	WRAPPED	6428BR	78 1/2	1994	SYNCHRONOUS	6773BR	54	1372	RAW EDGE	6590BR
105 7/8	2689	WRAPPED	6821BR	126	3200	WRAPPED	6867BR	54 3/4	1391	WRAPPED	6510BR
107 1/4	2723	DOUBLE V	6579BR	139 5/8	3546	WRAPPED	6998BR	54 3/4	1391	COGGED	6910BR
107 3/8	2727	WRAPPED	6781BR	146	3708	WRAPPED	7107BR	55 1/8	1400	WRAPPED	6419BR
107 1/2	2730	DOUBLE V	6456BR	147	3734	WRAPPED	7112BR	55 1/8	1400	RIBBED	6931BR
108 5/8	2759	WRAPPED	7053BR	148	3759	WRAPPED	6999BR	55 1/4	1403	WRAPPED	6564BR
109	2769	WRAPPED	7055BR	149	3785	WRAPPED	7108BR	56 1/4	1429	COGGED	6790BR
109 3/8	2777	WRAPPED	6663BR	151	3835	WRAPPED	7109BR	56 1/4	1429	WRAPPED	7040BR
110 1/4	2800	WRAPPED	6763BR	154	3912	WRAPPED	7113BR	56 1/4	1429	WRAPPED	6823BR
110 3/4	2813	WRAPPED	7029BR	155 3/4	3956	WRAPPED	7082BR	57 1/4	1454	WRAPPED	6823BR
112 3/8	2854	WRAPPED	6928BR	157	3988	WRAPPED	7110BR	57 7/8	1471	RIBBED	6666BR
113 1/4	2877	WRAPPED	6872BR	161 7/8	4112	WRAPPED	7083BR	58 3/4	1492	RIBBED	6742BR
113 5/8	2886	RAW EDGE	6900BR	163	4140	WRAPPED	7000BR	60 3/4	1543	WRAPPED	6406BR
114 1/4	2902	WRAPPED	6633BR	163 1/2	4153	WRAPPED	6936BR	61 1/8	1553	WRAPPED	6683BR
114 1/2	2908	WRAPPED	6684BR	166 5/8	4232	WRAPPED	6868BR	61 1/4	1556	WRAPPED	6854BR
115 3/4	2940	WRAPPED	6848BR	170	4318	WRAPPED	7034BR	62 1/4	1581	WRAPPED	6865BR
116 1/4	2953	DOUBLE V	7120BR	170 7/8	4340	WRAPPED	7001BR	63 1/4	1607	COGGED	6791BR
117 3/8	2981	WRAPPED	6923BR	173	4394	WRAPPED	6937BR	63 1/4	1607	WRAPPED	7106BR
117 5/8	2987	WRAPPED	6604BR	175	4445	WRAPPED	6885BR	64 1/4	1632	WRAPPED	6837BR
118 3/8	3007	WRAPPED	6715BR	176	4470	WRAPPED	6938BR	64 3/4	1645	WRAPPED	6464BR
119 3/8	3032	WRAPPED	6874BR	179 1/4	4553	WRAPPED	6869BR	65 1/8	1654	COGGED	6911BR
120 1/8	3053	WRAPPED	6481BR	182	4623	WRAPPED	7086BR	65 1/4	1657	WRAPPED	6996BR
120 5/8	3063	WRAPPED	6662BR	194 1/4	4934	WRAPPED	7111BR	65 3/4	1670	COGGED	7081BR
121 1/2	3086	WRAPPED	6945BR	199	5055	WRAPPED	6850BR	66 1/4	1683	WRAPPED	6855BR
122 1/8	3102	WRAPPED	6777BR	201	5105	WRAPPED	7002BR	67 1/2	1713	RIBBED	7128BR
122 1/2	3112	DOUBLE V	6409BR	202 3/4	5150	WRAPPED	7084BR	67 3/4	1721	WRAPPED	6502BR
123 1/4	3131	WRAPPED	6849BR	203 1/2	5169	WRAPPED	7085BR	67 7/8	1724	WRAPPED	6527BR
124	3150	RAW EDGE	6628BR	204 3/8	5191	WRAPPED	6870BR	68	1727	COGGED	7056BR
125 3/8	3185	WRAPPED	6977BR	219 1/4	5575	WRAPPED	6851BR	68	1727	WRAPPED	6482BR
126 1/2	3213	WRAPPED	6484BR	<b>21/32" (17 mm) Top Width</b>				68 1/4	1730	WRAPPED	6482BR
127 5/8	3243	WRAPPED	6486BR	32 1/2	825	WRAPPED	6618BR	68 5/8	1743	WRAPPED	6682BR
128 1/2	3264	WRAPPED	7100BR	35 1/2	902	WRAPPED	6494BR	69 1/4	1759	WRAPPED	6488BR
130 5/8	3318	WRAPPED	7089BR	35 1/2	902	WRAPPED	7050BR	69 1/2	1765	COGGED	6846BR
131 1/8	3331	WRAPPED	7090BR	35 3/4	906	WRAPPED	6554BR	69 7/8	1775	WRAPPED	6630BR
131 7/8	3350	WRAPPED	6727BR	36 7/8	937	WRAPPED	6617BR	70 1/4	1784	WRAPPED	6838BR
132 3/8	3362	WRAPPED	7117BR	38 1/2	979	WRAPPED	6511BR	71 1/4	1810	RAW EDGE	7030BR
134 3/8	3414	WRAPPED	6577BR	40 1/4	1022	COGGED	6989BR	71 3/4	1822	WRAPPED	6520BR
134 3/8	3413	WRAPPED	6842BR	41	1041	WRAPPED	7051BR	72 1/2	1842	COGGED	7066BR
136 1/8	3458	WRAPPED	7071BR	41 1/8	1045	WRAPPED	6514BR	72 3/4	1842	WRAPPED	6402BR
136 1/4	3486	WRAPPED	6978BR	41 1/2	1055	WRAPPED	6556BR	73 3/8	1915	WRAPPED	6675BR
137	3480	WRAPPED	7105BR	42 1/4	1073	COGGED	6990BR	76	1930	COGGED	7114BR
139 1/8	3534	WRAPPED	6652BR	42 7/8	1089	COGGED	6548BR	76 3/4	1949	WRAPPED	6644BR
140 3/8	3566	WRAPPED	7054BR	43 7/8	1114	COGGED	6738BR	77 1/4	1962	COGGED	6913BR
141 3/8	3591	WRAPPED	6686BR	44	1119	WRAPPED	6405BR	78	1981	WRAPPED	6408BR
141 3/8	3591	WRAPPED	6873BR					78	1981	WRAPPED	6555BR
142 3/8	3616	WRAPPED	6716BR					78 1/4	1988	WRAPPED	6840BR
143 1/2	3645	WRAPPED	6707BR					79 7/8	2029	COGGED	6739BR
144 1/8	3661	WRAPPED	6766BR					80 1/4	2038	WRAPPED	6815BR
144 5/8	3673	WRAPPED	7016BR					80 3/8	2041	WRAPPED	6647BR
145 1/8	3686	WRAPPED	7098BR					80 7/8	2054	RAW EDGE	6751BR
145 5/8	3699	WRAPPED	7118BR					81 1/4	2064	WRAPPED	6506BR
146 1/8	3712	WRAPPED	6708BR					81 3/8	2067	COGGED	6740BR



# BLADERUNNER® BELTS – LISTED BY SIZE

Length (in.)	Length (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Construction	Belt Number
<b>21/32" (17 mm) Top Width - Cont.</b>				<b>21/32" (17 mm) Top Width - Cont.</b>				<b>21/32" (17 mm) Top Width - Cont.</b>			
81 1/2	2071	RAW EDGE	6515BR	125 1/2	3188	WRAPPED	6905BR	179 1/4	4553	WRAPPED	7031BR
81 3/4	2077	WRAPPED	6592BR	126 7/8	3223	DOUBLE V.	6687BR	180 1/4	4578	WRAPPED	6844BR
82 1/4	2089	WRAPPED	6454BR	127 1/4	3232	WRAPPED	6901BR	180 7/8	4594	WRAPPED	6970BR
82 3/8	2092	WRAPPED	6573BR	128 3/8	3261	DOUBLE V.	6725BR	182 3/4	4642	WRAPPED	6902BR
83 1/4	2115	WRAPPED	6676BR	129	3274	WRAPPED	6568BR	183 3/8	4658	WRAPPED	6761BR
83 1/4	2115	WRAPPED	6705BR	129 1/4	3283	DOUBLE V.	7096BR	185 1/4	4705	WRAPPED	6880BR
83 1/4	2115	WRAPPED	6812BR	130 3/8	3312	WRAPPED	6992BR	185 3/4	4718	WRAPPED	6784BR
83 1/2	2121	RAW EDGE	6969BR	130 1/2	3315	DOUBLE V.	6789BR	186 1/4	4731	WRAPPED	6860BR
83 5/8	2124	WRAPPED	6467BR	131 1/2	3340	WRAPPED	6946BR	189 3/8	4810	WRAPPED	7042BR
83 5/8	2124	WRAPPED	6754BR	132	3353	DOUBLE V.	6748BR	190 3/8	4836	WRAPPED	6722BR
84 1/4	2140	WRAPPED	6866BR	133 1/8	3381	WRAPPED	6646BR	191 3/8	4861	WRAPPED	6920BR
85 1/4	2165	WRAPPED	6702BR	133 1/4	3385	DOUBLE V.	7064BR	193 1/2	4915	WRAPPED	7033BR
86 1/4	2191	WRAPPED	7068BR	133 3/8	3389	WRAPPED	6485BR	195	4953	WRAPPED	6803BR
86 3/4	2204	WRAPPED	6537BR	134	3404	WRAPPED	6778BR	196 3/8	4988	WRAPPED	6881BR
87 1/4	2216	WRAPPED	6814BR	135	3429	WRAPPED	6845BR	198 3/8	5039	WRAPPED	6934BR
87 3/4	2229	RAW EDGE	6591BR	135 1/2	3442	DOUBLE V.	6942BR	201	5105	WRAPPED	6882BR
88	2235	WRAPPED	6753BR	135 5/8	3445	WRAPPED	6785BR	202	5131	WRAPPED	6921BR
88 1/4	2242	WRAPPED	6839BR	135 3/4	3448	DOUBLE V.	6622BR	203 1/4	5163	WRAPPED	6883BR
88 7/8	2258	WRAPPED	6645BR	136 3/8	3464	WRAPPED	6982BR	204 5/8	5198	WRAPPED	6971BR
89 1/4	2266	WRAPPED	6614BR	136 1/2	3467	DOUBLE V.	6696BR	208 3/8	5293	WRAPPED	6935BR
89 3/4	2280	WRAPPED	6701BR	136 5/8	3470	WRAPPED	6596BR	211 1/4	5366	WRAPPED	6771BR
90 3/8	2294	WRAPPED	6649BR	137 1/2	3493	WRAPPED	6786BR	219	5563	WRAPPED	6947BR
90 1/2	2299	WRAPPED	6606BR	138 1/4	3512	WRAPPED	6779BR	219 5/8	5578	WRAPPED	6884BR
91 1/4	2318	WRAPPED	6704BR	140 1/4	3561	WRAPPED	6566BR	225 3/4	5734	WRAPPED	6693BR
91 1/4	2318	WRAPPED	7072BR	141	3581	WRAPPED	6906BR	235 1/2	5982	WRAPPED	6972BR
92 3/8	2346	DOUBLE V.	7060BR	142 1/8	3609	WRAPPED	6616BR	237 5/8	6036	WRAPPED	7043BR
93 1/4	2369	WRAPPED	6703BR	142 1/4	3614	WRAPPED	6599BR	242 3/8	6156	WRAPPED	6659BR
93 1/4	2369	WRAPPED	6816BR	143 3/8	3642	WRAPPED	6783BR	264 1/2	6718	WRAPPED	7059BR
93 1/4	2369	DOUBLE V.	7094BR	144	3658	WRAPPED	7057BR	<b>11/16" (18 mm) Top Width</b>			
94 1/4	2394	WRAPPED	6877BR	144 3/4	3677	WRAPPED	6744BR	35 1/8	892	COGGED	6680BR
95	2413	RAW EDGE	6991BR	145	3683	WRAPPED	6759BR	50	1270	RIBBED	7035BR
95 5/8	2429	WRAPPED	6806BR	145 5/8	3699	WRAPPED	6804BR	71	1803	RIBBED	7020BR
96 1/4	2445	WRAPPED	6856BR	145 7/8	3705	WRAPPED	6567BR	173 3/4	4413	WRAPPED	7129BR
97 1/4	2470	WRAPPED	6575BR	147 1/8	3737	WRAPPED	6787BR	<b>3/4" (19 mm) Top Width</b>			
97 1/4	2470	WRAPPED	6721BR	147 1/8	3737	WRAPPED	6800BR	58 1/2	1487	RIBBED	6543BR
99	2515	WRAPPED	6949BR	147 1/2	3747	WRAPPED	6729BR	<b>27/32" (21 mm) Top Width</b>			
100 1/2	2553	DOUBLE V.	7061BR	147 5/8	3750	WRAPPED	6767BR	32 1/8	816	RIBBED	6929BR
100 3/4	2559	WRAPPED	6416BR	148 3/8	3769	WRAPPED	6692BR	47 1/4	1200	RIBBED	6967BR
101 7/8	2586	WRAPPED	6480BR	149 1/2	3797	WRAPPED	7069BR	91	2311	BANDED	6951BR
102 1/4	2597	WRAPPED	6857BR	149 7/8	3807	WRAPPED	6745BR	<b>13/16" (21 mm) Top Width</b>			
103 3/8	2626	WRAPPED	6904BR	150	3810	DOUBLE V.	7065BR	34 5/8	880	BANDED	7122BR
103 7/8	2638	WRAPPED	6917BR	150 3/4	3829	WRAPPED	7093BR	41 1/4	1048	BANDED	7123BR
104 7/8	2664	WRAPPED	6994BR	151 1/2	3848	WRAPPED	6746BR	<b>7/8" (22 mm) Top Width</b>			
105 1/4	2673	RAW EDGE	6584BR	152	3864	WRAPPED	6732BR	57 3/4	1467	COGGED	6968BR
106 1/4	2699	WRAPPED	6858BR	152 1/4	3867	WRAPPED	6730BR	173 3/8	4404	WRAPPED	6762BR
107 5/8	2734	WRAPPED	6805BR	152 3/4	3880	WRAPPED	7070BR	175 3/4	4464	WRAPPED	7116BR
109	2769	DOUBLE V.	7077BR	153 5/8	3907	WRAPPED	6597BR	<b>29/32" (23 mm) Top Width</b>			
109 5/8	2785	WRAPPED	6492BR	153 7/8	3908	WRAPPED	6983BR	47 1/2	1207	WRAPPED	6984BR
110 3/4	2813	WRAPPED	7092BR	154 3/4	3931	WRAPPED	6719BR	<b>15/16" (24 mm) Top Width</b>			
111 3/8	2828	WRAPPED	6650BR	155 3/8	3947	WRAPPED	6892BR	28 5/8	727	RIBBED	6700BR
112	2845	DOUBLE V.	7078BR	156 1/4	3969	WRAPPED	6997BR	44 5/8	1133	RIBBED	6965BR
112 5/8	2861	DOUBLE V.	6694BR	156 3/8	3972	DOUBLE V.	6723BR	47 5/8	1210	RIBBED	6966BR
112 3/4	2863	WRAPPED	6615BR	157 1/4	3994	WRAPPED	6933BR	79 5/8	2022	RIBBED	7087BR
113 3/4	2889	WRAPPED	6980BR	158 1/4	4021	WRAPPED	6598BR	<b>1" (25 mm) Top Width</b>			
114 1/8	2899	WRAPPED	6916BR	159 5/8	4054	WRAPPED	7058BR	12 1/4	311	SYNCHRONOUS	6678BR
114 1/4	2902	DOUBLE V.	6749BR	160 1/4	4070	WRAPPED	6768BR	<b>1 3/32" (28 mm) Top Width</b>			
114 5/8	2911	WRAPPED	7041BR	161 1/4	4096	WRAPPED	6769BR	32 1/8	816	RIBBED	6699BR
114 3/4	2915	DOUBLE V.	7121BR	162 1/4	4121	WRAPPED	6859BR				
115 3/8	2930	WRAPPED	6665BR	162 5/8	4131	WRAPPED	6731BR				
115 1/2	2934	DOUBLE V.	7095BR	162 3/4	4134	WRAPPED	6741BR				
116 1/8	2950	WRAPPED	6728BR	163 1/2	4153	WRAPPED	6760BR				
117 1/4	2978	WRAPPED	6688BR	165	4191	WRAPPED	6853BR				
118 1/4	3004	DOUBLE V.	7062BR	165 3/8	4201	WRAPPED	6801BR				
118 3/8	3006	WRAPPED	6648BR	165 5/8	4207	WRAPPED	6733BR				
119	3023	WRAPPED	6752BR	167	4242	WRAPPED	7049BR				
119 1/4	3029	DOUBLE V.	6724BR	168	4267	WRAPPED	6747BR				
119 3/4	3042	WRAPPED	6981BR	168 1/4	4274	WRAPPED	6950BR				
120 1/4	3054	WRAPPED	6843BR	169 3/8	4303	WRAPPED	6569BR				
120 3/4	3067	DOUBLE V.	6788BR	169 7/8	4315	WRAPPED	6878BR				
121 1/4	3079	WRAPPED	6574BR	172 3/4	4388	WRAPPED	6770BR				
121 1/4	3080	WRAPPED	7048BR	174 5/8	4435	WRAPPED	6893BR				
122 3/8	3108	WRAPPED	6918BR	175 1/2	4458	WRAPPED	6720BR				
122 3/4	3118	DOUBLE V.	7079BR	175 7/8	4468	WRAPPED	6661BR				
123 5/8	3140	WRAPPED	6589BR	176 1/8	4474	WRAPPED	6879BR				
123 3/4	3143	DOUBLE V.	7063BR	176 3/4	4489	WRAPPED	6802BR				
124 1/4	3156	WRAPPED	6817BR	177 3/4	4515	WRAPPED	7032BR				
124 1/2	3162	DOUBLE V.	6695BR	178 3/8	4531	WRAPPED	6919BR				

② Set of Two Belts



**BLADERUNNER® BELTS – LISTED BY SIZE**



Length (in.)	Length (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Construction	Belt Number	Length (in.)	Length (mm)	Construction	Belt Number
<b>1 5/32" (29 mm) Top Width</b>				<b>1 1/4" (32 mm) Top Width - Cont.</b>				<b>1 5/8" (41 mm) Top Width</b>			
39 7/8	1013	BANDED.....	6903BR	34	864	BANDED.....	6808BR	65 5/8	1668	BANDED.....	6962BR
<b>1 3/16" (30 mm) Top Width</b>				41 1/4	1046	BANDED.....	6670BR	68	1727	BANDED.....	6955BR
49 7/8	1267	BANDED.....	7124BR	43 1/8	1095	BANDED.....	6539BR	69	1752	BANDED.....	6956BR
52 5/8	1337	BANDED.....	6794BR	45	1141	BANDED.....	6466BR	70	1778	BANDED.....	6957BR
55 23/32	1415	BANDED.....	7125BR	45 1/4	1149	BANDED.....	6813BR	71	1803	BANDED.....	6958BR
55 23/32	1415	BANDED.....	7126BR	49 1/4	1250	BANDED.....	6664BR	<b>1 21/32 (42 mm) Top Width</b>			
55 7/8	1419	BANDED.....	6593BR	50 1/8	1275	BANDED.....	6586BR	57 1/4	1454	RIBBED.....	7088BR
<b>1 7/32" (31 mm) Top Width</b>				51 5/8	1311	BANDED.....	6470BR	<b>2 1/32" (52 mm) Top Width</b>			
56 3/8	1432	BANDED.....	6959BR	52 1/4	1327	BANDED.....	6440BR	69	1753	BANDED.....	6963BR
57 7/8	1470	BANDED.....	6952BR	56 1/2	1435	BANDED.....	6436BR	77 7/8	1978	BANDED.....	6964BR
58 7/8	1495	BANDED.....	6953BR	58 7/8	1495	BANDED.....	7018BR				
59 3/8	1508	BANDED.....	6960BR	64 3/4	1645	BANDED.....	6772BR				
64	1626	BANDED.....	6961BR	72 1/4	1835	BANDED.....	7023BR				
69 1/8	1757	BANDED.....	6954BR	83	2108	BANDED.....	6625BR				
<b>1 1/4" (32 mm) Top Width</b>				104 3/8	2651	BANDED.....	7102BR				
33 1/2	851	BANDED.....	6538BR	112 1/4	2851	BANDED.....	6797BR				
				112 5/8	2861	BANDED.....	6796BR				
				119 3/8	3032	BANDED.....	7103BR				
				122 7/8	3121	BANDED.....	6795BR				
				136 3/8	3464	BANDED.....	7104BR				





## Showing Belt Numbers with Corresponding Nominal Outside Lengths and Top Widths

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
K040378HD	38 1/2	978	9/16	14	K060680HD	68 5/8	1742	13/16	20
K040388HD	39 3/8	999	9/16	14	K060685HD	69 1/8	1756	13/16	20
K040425HD	43 1/8	1095	9/16	14	K060690HD	69 5/8	1767	13/16	20
K040430HD	43 3/4	1111	9/16	14	K060696HD	70 1/8	1781	13/16	20
K040445HD	45 1/4	1148	9/16	14	K060714HD	72	1829	13/16	20
K040745HD	75 1/8	1907	9/16	14	K060716HD	72	1830	13/16	20
K040762HD	76 3/4	1950	9/16	14	K060723HD	72 7/8	1851	13/16	20
K050323HD	33	837	21/32	17	K060730HD	73 1/2	1867	13/16	20
K050336HD	34 1/4	871	21/32	17	K060735HD	74 1/8	1881	13/16	20
K050340HD	34 5/8	881	21/32	17	K060736HD	74 1/8	1882	13/16	20
K050345HD	35 1/4	894	21/32	17	K060739HD	74 1/2	1893	13/16	20
K050350HD	35 5/8	905	21/32	17	K060747HD	75 3/8	1914	13/16	20
K050360HD	36 3/4	932	21/32	17	K060772HD	77 3/4	1975	13/16	20
K050375HD	38 1/4	971	21/32	17	K060795HD	80 1/8	2034	13/16	20
K050380HD	38 3/4	983	21/32	17	K060806HD	81 1/8	2061	13/16	20
K050420HD	42 5/8	1084	21/32	17	K060810HD	81 5/8	2073	13/16	20
K060337HD	34 1/4	871	13/16	20	K060812HD	81 3/4	2076	13/16	20
K060340HD	34 3/4	881	13/16	20	K060828HD	83 3/8	2118	13/16	20
K060374HD	37 7/8	962	13/16	20	K060832HD	83 3/4	2127	13/16	20
K060390HD	39 3/4	1008	13/16	20	K060846HD	85 1/4	2164	13/16	20
K060393HD	39 7/8	1012	13/16	20	K060849HD	85 1/2	2171	13/16	20
K060400HD	40 3/4	1034	13/16	20	K060858HD	86 3/8	2193	13/16	20
K060408HD	41 1/2	1054	13/16	20	K060860HD	86 5/8	2201	13/16	20
K060415HD	42 1/8	1069	13/16	20	K060870HD	87 5/8	2225	13/16	20
K060420HD	42 1/2	1080	13/16	20	K060874HD	87 7/8	2233	13/16	20
K060425HD	43 1/8	1095	13/16	20	K060875HD	88 1/8	2238	13/16	20
K060435HD	44 1/8	1122	13/16	20	K060878HD	88 3/8	2245	13/16	20
K060439HD	44 1/2	1129	13/16	20	K060882HD	88 7/8	2257	13/16	20
K060450HD	45 5/8	1160	13/16	20	K060883HD	89	2261	13/16	20
K060455HD	46	1170	13/16	20	K060888HD	89 1/2	2273	13/16	20
K060458HD	46 3/8	1179	13/16	20	K060905HD	90 7/8	2308	13/16	20
K060470HD	47 5/8	1211	13/16	20	K060908HD	91 1/4	2319	13/16	20
K060478HD	48 1/4	1227	13/16	20	K060910HD	91 5/8	2329	13/16	20
K060480HD	48 5/8	1237	13/16	20	K060923HD	92 7/8	2360	13/16	20
K060483HD	48 7/8	1241	13/16	20	K060930HD	93 5/8	2377	13/16	20
K060490HD	49 1/2	1258	13/16	20	K060935HD	94	2387	13/16	20
K060495HD	50 1/8	1274	13/16	20	K060950HD	95 5/8	2428	13/16	20
K060500HD	50 3/4	1288	13/16	20	K060956HD	96 1/8	2440	13/16	20
K060505HD	51	1295	13/16	20	K060960HD	96 1/2	2453	13/16	20
K060509HD	51 1/2	1309	13/16	20	K060970HD	97 5/8	2480	13/16	20
K060516HD	52 1/8	1325	13/16	20	K060984HD	99	2513	13/16	20
K060520HD	52 3/4	1339	13/16	20	K060988HD	99 1/2	2526	13/16	20
K060523HD	52 7/8	1343	13/16	20	K060990HD	99 5/8	2531	13/16	20
K060525HD	53 3/8	1355	13/16	20	K060994HD	99 7/8	2537	13/16	20
K060529HD	53 1/2	1359	13/16	20	K060997HD	100 1/4	2546	13/16	20
K060532HD	53 7/8	1367	13/16	20	K061000HD	100 5/8	2555	13/16	20
K060539HD	54 1/2	1385	13/16	20	K061005HD	101 1/8	2568	13/16	20
K060547HD	55 1/4	1404	13/16	20	K061010HD	101 5/8	2581	13/16	20
K060555HD	56	1423	13/16	20	K061015HD	102 1/8	2593	13/16	20
K060557HD	56 1/4	1429	13/16	20	K061020HD	102 5/8	2605	13/16	20
K060559HD	56 1/2	1436	13/16	20	K061025HD	103	2615	13/16	20
K060560HD	56 5/8	1439	13/16	20	K061031HD	103 5/8	2633	13/16	20
K060568HD	57 3/8	1459	13/16	20	K061058HD	106 3/8	2701	13/16	20
K060569HD	57 1/2	1462	13/16	20	K061077HD	108 1/4	2750	13/16	20
K060575HD	58	1473	13/16	20	K061080HD	108 3/4	2761	13/16	20
K060578HD	58 3/8	1483	13/16	20	K061102HD	110 3/4	2814	13/16	20
K060586HD	59 1/4	1504	13/16	20	K061140HD	114 1/2	2910	13/16	20
K060588HD	59 3/8	1508	13/16	20	K061158HD	116 3/8	2956	13/16	20
K060594HD	60	1523	13/16	20	K061177HD	118 1/4	3004	13/16	20
K060598HD	60 3/8	1534	13/16	20	K061187HD	119 1/4	3030	13/16	20
K060605HD	61 1/8	1553	13/16	20	K061195HD	120 1/8	3051	13/16	20
K060609HD	61 1/2	1563	13/16	20	K061203HD	120 7/8	3070	13/16	20
K060615HD	62 1/8	1577	13/16	20	K061223HD	122 7/8	3121	13/16	20
K060625HD	63 1/8	1603	13/16	20	K061251HD	125 5/8	3192	13/16	20
K060628HD	63 3/8	1610	13/16	20	K061265HD	127 1/8	3229	13/16	20
K060631HD	63 3/4	1619	13/16	20	K061360HD	136 1/2	3467	13/16	20
K060635HD	64 1/8	1627	13/16	20	K061369HD	137 1/2	3493	13/16	20
K060637HD	64 3/8	1634	13/16	20	K061373HD	137 7/8	3502	13/16	20
K060640HD	64 5/8	1641	13/16	20	K061380HD	138 5/8	3521	13/16	20
K060653HD	65 7/8	1674	13/16	20	K070404HD	41	1042	15/16	24
K060658HD	66 3/8	1687	13/16	20	K070529HD	53	1359	15/16	24
K060660HD	66 3/4	1696	13/16	20	K070553HD	55 7/8	1418	15/16	24
K060670HD	67 1/2	1716	13/16	20	K070640HD	64 5/8	1642	15/16	24
K060672HD	67 3/4	1722	13/16	20	K070673HD	67 3/4	1722	15/16	24
K060675HD	68	1728	13/16	20	K070677HD	68 1/4	1734	15/16	24

Size Lists

# FLEETRUNNER® MICRO-V® BELTS – LISTED BY NUMBER



Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
K070705HD	71 1/8	1807	15/16	24	K080702HD	70 3/4	1798	1 3/32	28
K070709HD	71 1/2	1816	15/16	24	K080708HD	71 1/4	1811	1 3/32	28
K070733HD	73 3/4	1874	15/16	24	K080710HD	71 1/2	1816	1 3/32	28
K070735HD	74 1/8	1883	15/16	24	K080712HD	71 3/4	1822	1 3/32	28
K070762HD	76 3/4	1949	15/16	24	K080716HD	72 1/8	1831	1 3/32	28
K070786HD	79 1/8	2011	15/16	24	K080718HD	72 3/8	1839	1 3/32	28
K070801HD	80 3/4	2051	15/16	24	K080720HD	72 5/8	1845	1 3/32	28
K070805HD	81 1/8	2061	15/16	24	K080723HD	72 7/8	1851	1 3/32	28
K070825HD	83 1/8	2112	15/16	24	K080726HD	73 1/4	1859	1 3/32	28
K070834HD	84	2133	15/16	24	K080730HD	73 1/2	1867	1 3/32	28
K070835HD	84	2134	15/16	24	K080733HD	73 3/4	1874	1 3/32	28
K070846HD	85 1/4	2164	15/16	24	K080734HD	74	1880	1 3/32	28
K071013HD	101 3/4	2584	15/16	24	K080738HD	74 3/8	1889	1 3/32	28
K071056HD	106 1/4	2699	15/16	24	K080740HD	74 5/8	1896	1 3/32	28
K071213HD	121 7/8	3096	15/16	24	K080745HD	75 1/8	1907	1 3/32	28
K071247HD	125 3/8	3183	15/16	24	K080751HD	75 5/8	1921	1 3/32	28
K080330HD	33 3/4	856	1 3/32	28	K080755HD	76	1931	1 3/32	28
K080375HD	38 1/8	968	1 3/32	28	K080760HD	76 1/2	1942	1 3/32	28
K080382HD	38 3/4	983	1 3/32	28	K080765HD	77	1957	1 3/32	28
K080384HD	39	990	1 3/32	28	K080770HD	77 1/2	1969	1 3/32	28
K080385HD	39 1/8	992	1 3/32	28	K080774HD	77 3/4	1976	1 3/32	28
K080400HD	40 3/4	1034	1 3/32	28	K080776HD	78 1/8	1985	1 3/32	28
K080415HD	42 1/8	1069	1 3/32	28	K080780HD	78 5/8	1996	1 3/32	28
K080427HD	43 1/2	1103	1 3/32	28	K080785HD	79	2007	1 3/32	28
K080433HD	43 7/8	1115	1 3/32	28	K080790HD	79 1/2	2019	1 3/32	28
K080435HD	44 1/8	1122	1 3/32	28	K080791HD	79 5/8	2022	1 3/32	28
K080450HD	45 5/8	1160	1 3/32	28	K080794HD	80	2032	1 3/32	28
K080465HD	47	1195	1 3/32	28	K080797HD	80 1/8	2037	1 3/32	28
K080468HD	47 3/8	1203	1 3/32	28	K080801HD	80 3/4	2050	1 3/32	28
K080471HD	47 3/4	1211	1 3/32	28	K080806HD	81 1/8	2061	1 3/32	28
K080480HD	48 5/8	1237	1 3/32	28	K080808HD	81 3/8	2067	1 3/32	28
K080485HD	49 1/8	1249	1 3/32	28	K080810HD	81 5/8	2073	1 3/32	28
K080496HD	50 1/8	1274	1 3/32	28	K080813HD	81 3/8	2080	1 3/32	28
K080505HD	51	1297	1 3/32	28	K080816HD	82 1/8	2086	1 3/32	28
K080510HD	51 1/2	1309	1 3/32	28	K080817HD	82 3/8	2091	1 3/32	28
K080514HD	52	1320	1 3/32	28	K080820HD	82 3/4	2100	1 3/32	28
K080525HD	53 1/8	1351	1 3/32	28	K080825HD	83 1/8	2112	1 3/32	28
K080530HD	53 1/2	1359	1 3/32	28	K080830HD	83 3/4	2127	1 3/32	28
K080537HD	54 1/4	1379	1 3/32	28	K080834HD	84	2134	1 3/32	28
K080539HD	54 1/2	1384	1 3/32	28	K080839HD	84 3/8	2144	1 3/32	28
K080545HD	55 1/8	1399	1 3/32	28	K080842HD	84 3/4	2154	1 3/32	28
K080550HD	55 3/4	1415	1 3/32	28	K080845HD	85 1/8	2161	1 3/32	28
K080553HD	55 7/8	1419	1 3/32	28	K080850HD	85 3/8	2175	1 3/32	28
K080560HD	56 5/8	1439	1 3/32	28	K080852HD	85 3/4	2178	1 3/32	28
K080565HD	57	1448	1 3/32	28	K080855HD	86 1/8	2187	1 3/32	28
K080566HD	57 1/8	1452	1 3/32	28	K080859HD	86 3/8	2195	1 3/32	28
K080570HD	57 1/2	1462	1 3/32	28	K080860HD	86 5/8	2200	1 3/32	28
K080575HD	58 1/8	1475	1 3/32	28	K080865HD	87 1/8	2212	1 3/32	28
K080580HD	58 5/8	1490	1 3/32	28	K080868HD	87 3/8	2219	1 3/32	28
K080585HD	59	1499	1 3/32	28	K080872HD	87 3/4	2230	1 3/32	28
K080590HD	59 1/2	1512	1 3/32	28	K080876HD	88 1/8	2240	1 3/32	28
K080594HD	60	1523	1 3/32	28	K080878HD	88 3/8	2245	1 3/32	28
K080600HD	60 5/8	1538	1 3/32	28	K080885HD	89 1/8	2263	1 3/32	28
K080605HD	61 1/8	1553	1 3/32	28	K080889HD	89 1/2	2272	1 3/32	28
K080610HD	61 3/4	1569	1 3/32	28	K080893HD	89 7/8	2282	1 3/32	28
K080615HD	62 1/8	1577	1 3/32	28	K080897HD	90 3/8	2295	1 3/32	28
K080616HD	62 1/4	1581	1 3/32	28	K080903HD	90 7/8	2308	1 3/32	28
K080618HD	62 3/8	1584	1 3/32	28	K080910HD	91 5/8	2326	1 3/32	28
K080620HD	62 5/8	1591	1 3/32	28	K080913HD	91 7/8	2334	1 3/32	28
K080623HD	62 7/8	1598	1 3/32	28	K080915HD	92 1/8	2340	1 3/32	28
K080626HD	63 1/8	1603	1 3/32	28	K080922HD	92 3/4	2355	1 3/32	28
K080627HD	63 1/2	1613	1 3/32	28	K080926HD	93 1/8	2367	1 3/32	28
K080630HD	63 5/8	1616	1 3/32	28	K080931HD	93 5/8	2379	1 3/32	28
K080638HD	64 3/8	1634	1 3/32	28	K080934HD	93 7/8	2384	1 3/32	28
K080645HD	65 1/4	1657	1 3/32	28	K080939HD	94 1/2	2400	1 3/32	28
K080649HD	65 1/2	1665	1 3/32	28	K080944HD	95	2412	1 3/32	28
K080653HD	65 7/8	1674	1 3/32	28	K080948HD	95 3/8	2423	1 3/32	28
K080657HD	66 1/4	1683	1 3/32	28	K080952HD	95 3/4	2432	1 3/32	28
K080660HD	66 1/2	1691	1 3/32	28	K080956HD	96 1/4	2444	1 3/32	28
K080662HD	66 3/4	1695	1 3/32	28	K080962HD	96 3/4	2457	1 3/32	28
K080665HD	67 1/8	1705	1 3/32	28	K080964HD	97	2465	1 3/32	28
K080670HD	67 1/2	1716	1 3/32	28	K080968HD	97 1/2	2475	1 3/32	28
K080672HD	67 3/4	1722	1 3/32	28	K080976HD	98 1/4	2496	1 3/32	28
K080675HD	68	1728	1 3/32	28	K080986HD	99 1/8	2519	1 3/32	28
K080677HD	68 1/4	1734	1 3/32	28	K080991HD	99 5/8	2531	1 3/32	28
K080680HD	68 5/8	1742	1 3/32	28	K080994HD	100	2540	1 3/32	28
K080683HD	68 7/8	1750	1 3/32	28	K081000HD	100 5/8	2555	1 3/32	28
K080685HD	69 1/8	1756	1 3/32	28	K081005HD	101 1/8	2568	1 3/32	28
K080690HD	69 5/8	1767	1 3/32	28	K081015HD	102 1/8	2594	1 3/32	28
K080694HD	70	1777	1 3/32	28	K081020HD	102 5/8	2605	1 3/32	28
K080700HD	70 1/2	1789	1 3/32	28	K081023HD	102 7/8	2613	1 3/32	28



# FLEETRANNER® MICRO-V® BELTS – LISTED BY NUMBER

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
K081025HD	103 1/8	2619	1 3/32	28	K100649HD	65 1/2	1664	1 3/8	35
K081032HD	103 3/4	2635	1 3/32	28	K100655HD	66	1678	1 3/8	35
K081035HD	104	2642	1 3/32	28	K100658HD	66 3/8	1687	1 3/8	35
K081040HD	104 3/4	2660	1 3/32	28	K100661HD	66 3/4	1694	1 3/8	35
K081044HD	105	2666	1 3/32	28	K100665HD	67 1/8	1704	1 3/8	35
K081047HD	105 1/4	2673	1 3/32	28	K100670HD	67 1/2	1716	1 3/8	35
K081051HD	105 3/4	2686	1 3/32	28	K100675HD	68	1728	1 3/8	35
K081055HD	106 1/8	2694	1 3/32	28	K100677HD	68 1/4	1734	1 3/8	35
K081059HD	106 1/2	2705	1 3/32	28	K100686HD	69 1/4	1758	1 3/8	35
K081062HD	106 7/8	2715	1 3/32	28	K100694HD	70	1778	1 3/8	35
K081065HD	107 1/8	2720	1 3/32	28	K100702HD	70 7/8	1800	1 3/8	35
K081074HD	108	2745	1 3/32	28	K100706HD	71 1/4	1810	1 3/8	35
K081079HD	108 1/2	2756	1 3/32	28	K100710HD	71 1/2	1816	1 3/8	35
K081088HD	109 3/8	2778	1 3/32	28	K100714HD	72	1829	1 3/8	35
K081092HD	109 3/4	2788	1 3/32	28	K100719HD	72 3/8	1840	1 3/8	35
K081099HD	110 1/2	2807	1 3/32	28	K100720HD	72 5/8	1845	1 3/8	35
K081102HD	110 3/4	2814	1 3/32	28	K100726HD	73 1/8	1859	1 3/8	35
K081124HD	113	2869	1 3/32	28	K100731HD	73 5/8	1871	1 3/8	35
K081131HD	113 3/4	2889	1 3/32	28	K100739HD	74 1/2	1893	1 3/8	35
K081153HD	116 1/4	2953	1 3/32	28	K100745HD	75 1/8	1907	1 3/8	35
K081177HD	118 1/4	3005	1 3/32	28	K100749HD	75 1/2	1918	1 3/8	35
K081189HD	119 1/2	3034	1 3/32	28	K100761HD	76 3/4	1949	1 3/8	35
K081196HD	120 1/8	3050	1 3/32	28	K100764HD	77	1957	1 3/8	35
K081207HD	121 3/8	3082	1 3/32	28	K100771HD	77 3/4	1976	1 3/8	35
K081213HD	121 7/8	3096	1 3/32	28	K100789HD	79 1/2	2019	1 3/8	35
K081223HD	122 3/4	3117	1 3/32	28	K100810HD	81 5/8	2073	1 3/8	35
K081243HD	124 7/8	3172	1 3/32	28	K100814HD	82	2083	1 3/8	35
K081264HD	127	3227	1 3/32	28	K100816HD	82 1/8	2086	1 3/8	35
K081265HD	127 1/8	3228	1 3/32	28	K100818HD	82 1/2	2096	1 3/8	35
K081298HD	130 3/8	3312	1 3/32	28	K100822HD	82 3/4	2102	1 3/8	35
K081304HD	131	3327	1 3/32	28	K100830HD	83 5/8	2124	1 3/8	35
K081325HD	133 1/8	3381	1 3/32	28	K100852HD	85 7/8	2182	1 3/8	35
K081331HD	133 3/4	3396	1 3/32	28	K100860HD	86 5/8	2200	1 3/8	35
K081348HD	135 3/8	3439	1 3/32	28	K100864HD	87	2210	1 3/8	35
K081359HD	136 1/2	3468	1 3/32	28	K100870HD	87 5/8	2226	1 3/8	35
K081362HD	136 3/4	3474	1 3/32	28	K100874HD	88	2235	1 3/8	35
K081369HD	137 1/2	3492	1 3/32	28	K100877HD	88 1/4	2242	1 3/8	35
K081377HD	138 1/4	3513	1 3/32	28	K100879HD	88 1/2	2247	1 3/8	35
K090490HD	49 1/2	1258	1 7/32	31	K100884HD	89	2261	1 3/8	35
K090500HD	50 1/2	1282	1 7/32	31	K100885HD	89 1/8	2264	1 3/8	35
K090578HD	58 3/8	1482	1 7/32	31	K100891HD	89 3/4	2278	1 3/8	35
K090586HD	59 1/4	1504	1 7/32	31	K100894HD	90	2285	1 3/8	35
K090609HD	61 1/2	1562	1 7/32	31	K100921HD	92 5/8	2354	1 3/8	35
K090613HD	62	1573	1 7/32	31	K100935HD	94	2388	1 3/8	35
K100381HD	38 3/4	983	1 3/8	35	K100946HD	95 1/4	2419	1 3/8	35
K100437HD	44 1/4	1124	1 3/8	35	K100950HD	95 5/8	2428	1 3/8	35
K100456HD	46 1/8	1173	1 3/8	35	K100953HD	95 7/8	2436	1 3/8	35
K100465HD	47	1195	1 3/8	35	K100955HD	96	2438	1 3/8	35
K100485HD	48 7/8	1241	1 3/8	35	K100976HD	98 1/4	2496	1 3/8	35
K100495HD	50 1/8	1274	1 3/8	35	K100983HD	98 7/8	2511	1 3/8	35
K100502HD	50 3/4	1288	1 3/8	35	K100994HD	100	2539	1 3/8	35
K100510HD	51 1/2	1309	1 3/8	35	K100998HD	100 3/8	2550	1 3/8	35
K100529HD	53 3/8	1356	1 3/8	35	K101005HD	101 1/8	2569	1 3/8	35
K100535HD	54	1373	1 3/8	35	K101010HD	101 1/2	2579	1 3/8	35
K100540HD	54 1/2	1385	1 3/8	35	K101015HD	102	2591	1 3/8	35
K100551HD	55 5/8	1414	1 3/8	35	K101066HD	107 1/8	2721	1 3/8	35
K100554HD	56	1423	1 3/8	35	K101078HD	108 3/8	2753	1 3/8	35
K100557HD	56 3/8	1432	1 3/8	35	K101091HD	109 5/8	2786	1 3/8	35
K100563HD	56 7/8	1444	1 3/8	35	K101096HD	110 1/8	2797	1 3/8	35
K100564HD	57	1448	1 3/8	35	K101115HD	112	2846	1 3/8	35
K100570HD	57 1/2	1462	1 3/8	35	K101331HD	133 3/4	3397	1 3/8	35
K100572HD	57 7/8	1469	1 3/8	35	K120281HD	28 3/4	730	1 21/32	42
K100575HD	58 1/8	1475	1 3/8	35	K120360HD	36 5/8	929	1 21/32	42
K100578HD	58 3/8	1482	1 3/8	35	K120390HD	39 3/4	1008	1 21/32	42
K100579HD	58 1/2	1487	1 3/8	35	K120400HD	40 3/4	1034	1 21/32	42
K100582HD	58 3/4	1492	1 3/8	35	K120410HD	41 1/2	1054	1 21/32	42
K100586HD	59 1/4	1505	1 3/8	35	K120457HD	46 1/4	1175	1 21/32	42
K100594HD	60	1523	1 3/8	35	K120463HD	46 7/8	1191	1 21/32	42
K100600HD	60 1/2	1538	1 3/8	35	K120476HD	48 1/4	1226	1 21/32	42
K100601HD	60 7/8	1546	1 3/8	35	K120483HD	48 7/8	1241	1 21/32	42
K100604HD	61 1/8	1550	1 3/8	35	K120525HD	53 1/8	1351	1 21/32	42
K100607HD	61 1/4	1557	1 3/8	35	K120559HD	56 1/2	1436	1 21/32	42
K100610HD	61 5/8	1564	1 3/8	35	K120594HD	60	1523	1 21/32	42
K100613HD	61 7/8	1572	1 3/8	35	K120606HD	61 1/8	1553	1 21/32	42
K100615HD	62	1576	1 3/8	35	K120610HD	61 3/4	1569	1 21/32	42
K100618HD	62 3/8	1585	1 3/8	35	K120640HD	64 5/8	1641	1 21/32	42
K100630HD	63 5/8	1616	1 3/8	35	K120645HD	65	1651	1 21/32	42
K100635HD	64 3/4	1633	1 3/8	35	K120664HD	67 5/32	1706	1 21/32	42
K100637HD	64 1/4	1633	1 3/8	35	K120671HD	67 5/8	1718	1 21/32	42
K100640HD	64 5/8	1642	1 3/8	35	K120702HD	70 3/4	1798	1 21/32	42
K100643HD	65	1651	1 3/8	35	K120720HD	72 5/8	1845	1 21/32	42

Size Lists

FLEETRUNNER® MICRO-V® BELTS – LISTED BY NUMBER



Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
K120729HD	73 1/2	1867	1 21/32	42	K120964HD	97	2463	1 21/32	42
K120732HD	73 3/4	1873	1 21/32	42	K120975HD	98 1/8	2492	1 21/32	42
K120734HD	74	1880	1 21/32	42	K120980HD	98 1/2	2503	1 21/32	42
K120738HD	74 3/8	1889	1 21/32	42	K120985HD	99 1/8	2516	1 21/32	42
K120774HD	78	1982	1 21/32	42	K120992HD	99 7/8	2537	1 21/32	42
K120784HD	79	2007	1 21/32	42	K121000HD	100 5/8	2556	1 21/32	42
K120786HD	79 1/8	2010	1 21/32	42	K121039HD	104 1/2	2654	1 21/32	42
K120815HD	82	2083	1 21/32	42	K121049HD	105 1/2	2680	1 21/32	42
K120825HD	83 1/8	2111	1 21/32	42	K121124HD	113	2870	1 21/32	42
K120842HD	84 3/4	2154	1 21/32	42	K121139HD	114 1/2	2909	1 21/32	42
K120852HD	85 3/4	2178	1 21/32	42	K140279HD	28 1/2	723	1 15/16	49
K120855HD	86 1/8	2188	1 21/32	42	K140345HD	35	890	1 15/16	49
K120858HD	86 3/8	2194	1 21/32	42	K140370HD	37 1/2	954	1 15/16	49
K120864HD	86 7/8	2208	1 21/32	42	K140429HD	43 1/2	1106	1 15/16	49
K120866HD	87 1/4	2215	1 21/32	42	K140433HD	43 7/8	1116	1 15/16	49
K120870HD	87 5/8	2225	1 21/32	42	K140451HD	45 5/8	1160	1 15/16	49
K120872HD	87 3/4	2230	1 21/32	42	K140496HD	50 1/8	1274	1 15/16	49
K120876HD	88 1/8	2239	1 21/32	42	K140516HD	52 1/8	1325	1 15/16	49
K120878HD	88 3/8	2245	1 21/32	42	K140524HD	53 1/8	1350	1 15/16	49
K120891HD	89 5/8	2278	1 21/32	42	K140555HD	56	1422	1 15/16	49
K120895HD	90 1/8	2289	1 21/32	42	K140580HD	58 5/8	1490	1 15/16	49
K120901HD	90 5/8	2301	1 21/32	42	K140594HD	60	1523	1 15/16	49
K120903HD	90 7/8	2308	1 21/32	42	K140597HD	60 3/8	1534	1 15/16	49
K120905HD	91 1/8	2315	1 21/32	42	K140603HD	60 7/8	1546	1 15/16	49
K120910HD	91 5/8	2326	1 21/32	42	K140618HD	62 3/8	1585	1 15/16	49
K120911HD	91 3/4	2329	1 21/32	42	K140627HD	63 3/8	1609	1 15/16	49
K120915HD	92 1/8	2340	1 21/32	42	K140662HD	66 3/4	1696	1 15/16	49
K120919HD	92 1/2	2350	1 21/32	42	K140682HD	68 3/4	1746	1 15/16	49
K120924HD	93 1/8	2364	1 21/32	42	K140700HD	70 1/2	1789	1 15/16	49
K120931HD	93 3/4	2381	1 21/32	42	K150680HD	68 5/8	1743	2 1/16	53
K120945HD	95	2415	1 21/32	42	K150730HD	73 1/2	1867	2 1/16	53



## Showing Nominal Belt Top Widths and Outside Lengths with Our Corresponding Belt Numbers

Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>9/16" (14 mm) Top Width</b>			<b>13/16" (20 mm) Top Width - Cont.</b>			<b>13/16" (20 mm) Top Width - Cont.</b>		
38 1/2	978	K040378HD	64 3/8	1634	K060637HD	125 5/8	3192	K061251HD
39 3/8	999	K040388HD	64 5/8	1641	K060640HD	127 1/8	3229	K061265HD
43 1/8	1095	K040425HD	65 7/8	1674	K060653HD	136 1/2	3467	K061360HD
43 3/4	1111	K040430HD	66 3/8	1687	K060658HD	137 1/2	3493	K061369HD
45 1/4	1148	K040445HD	66 3/4	1696	K060660HD	137 7/8	3502	K061373HD
75 1/8	1907	K040745HD	67 1/2	1716	K060670HD	138 5/8	3521	K061380HD
76 3/4	1950	K040762HD	67 3/4	1722	K060672HD	<b>15/16" (24 mm) Top Width</b>		
<b>21/32" (17 mm) Top Width</b>			68	1728	K060675HD	41	1042	K070404HD
33	837	K050323HD	68 5/8	1742	K060680HD	53	1359	K070529HD
34 1/4	871	K050336HD	69 1/8	1756	K060685HD	55 7/8	1418	K070553HD
34 5/8	881	K050340HD	69 5/8	1767	K060690HD	64 5/8	1642	K070640HD
35 1/4	894	K050345HD	70 1/8	1781	K060696HD	67 3/4	1722	K070673HD
35 5/8	905	K050350HD	72	1829	K060714HD	68 1/4	1734	K070677HD
36 3/4	932	K050360HD	72	1830	K060716HD	71 1/8	1807	K070705HD
38 1/4	971	K050375HD	72 7/8	1851	K060723HD	71 1/2	1816	K070709HD
38 3/4	983	K050380HD	73 1/2	1867	K060730HD	73 3/4	1874	K070733HD
42 5/8	1084	K050420HD	74 1/8	1881	K060735HD	74 1/8	1883	K070735HD
<b>13/16" (20 mm) Top Width</b>			74 1/2	1893	K060739HD	76 3/4	1949	K070762HD
34 1/4	871	K060337HD	75 3/8	1914	K060747HD	79 1/8	2011	K070786HD
34 3/4	881	K060340HD	77 3/4	1975	K060772HD	80 3/4	2051	K070801HD
37 7/8	962	K060374HD	80 1/8	2034	K060795HD	81 1/8	2061	K070805HD
39 3/4	1008	K060390HD	81 1/8	2061	K060806HD	83 1/8	2112	K070825HD
39 7/8	1012	K060393HD	81 5/8	2073	K060810HD	84	2133	K070834HD
40 3/4	1034	K060400HD	81 3/4	2076	K060812HD	84	2134	K070835HD
41 1/2	1054	K060408HD	83 3/8	2118	K060828HD	85 1/4	2164	K070846HD
42 1/8	1069	K060415HD	83 3/4	2127	K060832HD	101 3/4	2584	K071013HD
42 1/2	1080	K060420HD	85 1/4	2164	K060846HD	106 1/4	2699	K071056HD
43 1/8	1095	K060425HD	85 1/2	2171	K060849HD	121 7/8	3096	K071213HD
44 1/8	1122	K060435HD	86 3/8	2193	K060858HD	125 3/8	3183	K071247HD
44 1/2	1129	K060439HD	86 5/8	2201	K060860HD	<b>1 3/32" (28 mm) Top Width</b>		
45 5/8	1160	K060450HD	87 5/8	2225	K060870HD	33 3/4	856	K080330HD
46	1170	K060455HD	87 7/8	2233	K060874HD	38 1/8	968	K080375HD
46 3/8	1179	K060458HD	88 1/8	2238	K060875HD	38 3/4	983	K080382HD
47 5/8	1211	K060470HD	88 3/8	2245	K060878HD	39	990	K080384HD
48 1/4	1227	K060478HD	88 7/8	2257	K060882HD	39 1/8	992	K080385HD
48 5/8	1237	K060480HD	89	2261	K060883HD	40 3/4	1034	K080400HD
48 7/8	1241	K060483HD	89 1/2	2273	K060888HD	42 1/8	1069	K080415HD
49 1/2	1258	K060490HD	90 7/8	2308	K060905HD	43 1/2	1103	K080427HD
49 1/8	1258	K060490HD	91 1/4	2319	K060908HD	43 7/8	1115	K080433HD
50 1/8	1274	K060495HD	91 5/8	2329	K060910HD	44 1/8	1122	K080435HD
50 3/4	1288	K060500HD	92 7/8	2360	K060923HD	45 5/8	1160	K080450HD
51	1295	K060505HD	93 5/8	2377	K060930HD	47	1195	K080465HD
51 1/2	1309	K060509HD	94	2387	K060935HD	47 3/8	1203	K080468HD
52 1/8	1325	K060516HD	95 5/8	2428	K060950HD	47 3/4	1211	K080471HD
52 3/4	1339	K060520HD	96 1/8	2440	K060956HD	48 5/8	1237	K080480HD
52 7/8	1343	K060523HD	96 1/2	2453	K060960HD	49 1/8	1249	K080485HD
53 3/8	1355	K060525HD	97 5/8	2480	K060970HD	50 1/8	1274	K080496HD
53 1/2	1359	K060529HD	99	2513	K060984HD	51	1297	K080505HD
53 7/8	1367	K060532HD	99 1/2	2526	K060988HD	51 1/2	1309	K080510HD
54 1/2	1385	K060539HD	99 5/8	2531	K060990HD	52	1320	K080514HD
55 1/4	1404	K060547HD	99 7/8	2537	K060994HD	53 1/8	1351	K080525HD
56	1423	K060555HD	100 1/4	2546	K060997HD	53 1/2	1359	K080530HD
56 1/4	1429	K060557HD	100 5/8	2555	K061000HD	54 1/4	1379	K080537HD
56 1/2	1436	K060559HD	101 1/8	2568	K061005HD	54 1/2	1384	K080539HD
56 5/8	1439	K060560HD	101 5/8	2581	K061010HD	55 1/8	1399	K080545HD
57 3/8	1459	K060568HD	102 1/8	2593	K061015HD	55 3/4	1415	K080550HD
57 1/2	1462	K060569HD	102 5/8	2605	K061020HD	55 7/8	1419	K080553HD
58	1473	K060575HD	103	2615	K061025HD	56 5/8	1439	K080560HD
58 3/8	1483	K060578HD	103 5/8	2633	K061031HD	57	1448	K080565HD
59 1/4	1504	K060586HD	106 3/8	2701	K061058HD	57 1/8	1452	K080566HD
59 3/8	1508	K060588HD	108 1/4	2750	K061077HD	57 1/2	1462	K080570HD
60	1523	K060594HD	108 3/4	2761	K061080HD	58 1/8	1475	K080575HD
60 3/8	1534	K060598HD	110 3/4	2814	K061102HD	58 5/8	1490	K080580HD
61 1/8	1553	K060605HD	114 1/2	2910	K061140HD	59	1499	K080585HD
61 1/2	1563	K060609HD	116 3/8	2956	K061158HD	59 1/2	1512	K080590HD
62 1/8	1577	K060615HD	118 1/4	3004	K061177HD	60	1523	K080594HD
63 1/8	1603	K060625HD	119 1/4	3030	K061187HD	60 5/8	1538	K080600HD
63 3/8	1610	K060628HD	120 1/8	3051	K061195HD			
63 3/4	1619	K060631HD	120 7/8	3070	K061203HD			
64 1/8	1627	K060635HD	122 7/8	3121	K061223HD			

Size Lists



FLEETRUNNER® MICRO-V® BELTS – LISTED BY SIZE



Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>1 3/32" (28 mm) Top Width - Cont.</b>			<b>1 3/32" (28 mm) Top Width - Cont.</b>			<b>1 7/32" (31 mm) Top Width - Cont.</b>		
61 1/8	1553	K080605HD	87 3/4	2230	K080872HD	61 1/2	1562	K090609HD
61 3/4	1569	K080610HD	88 1/8	2240	K080876HD	62	1573	K090613HD
62 1/8	1577	K080615HD	88 3/8	2245	K080878HD	<b>1 3/8" (35 mm) Top Width</b>		
62 1/4	1581	K080616HD	89 1/8	2263	K080885HD	38 3/4	983	K100381HD
62 3/8	1584	K080618HD	89 1/2	2272	K080889HD	44 1/4	1124	K100437HD
62 5/8	1591	K080620HD	89 7/8	2282	K080893HD	46 1/8	1173	K100456HD
62 7/8	1598	K080623HD	90 3/8	2295	K080897HD	47	1195	K100465HD
63 1/8	1603	K080626HD	90 7/8	2308	K080903HD	48 7/8	1241	K100485HD
63 1/2	1613	K080627HD	91 5/8	2326	K080910HD	50 1/8	1274	K100495HD
63 5/8	1616	K080630HD	91 7/8	2334	K080913HD	50 3/4	1288	K100502HD
64 3/8	1634	K080638HD	92 1/8	2340	K080915HD	51 1/2	1309	K100510HD
65 1/4	1657	K080645HD	92 3/4	2355	K080922HD	53 3/8	1356	K100529HD
65 1/2	1665	K080649HD	93 1/8	2367	K080926HD	54	1373	K100535HD
65 7/8	1674	K080653HD	93 5/8	2379	K080931HD	54 1/2	1385	K100540HD
66 1/4	1683	K080657HD	93 7/8	2384	K080934HD	55 5/8	1414	K100551HD
66 1/2	1691	K080660HD	94 1/2	2400	K080939HD	56	1423	K100554HD
66 3/4	1695	K080662HD	95	2412	K080944HD	56 3/8	1432	K100557HD
67 1/8	1705	K080665HD	95 3/8	2423	K080948HD	56 7/8	1444	K100563HD
67 1/2	1716	K080670HD	95 3/4	2432	K080952HD	57	1448	K100564HD
67 3/4	1722	K080672HD	96 1/4	2444	K080956HD	57 1/2	1462	K100570HD
68	1728	K080675HD	96 3/4	2457	K080962HD	57 7/8	1469	K100572HD
68 1/4	1734	K080677HD	97	2465	K080964HD	58 1/8	1475	K100575HD
68 5/8	1742	K080680HD	97 1/2	2475	K080968HD	58 3/8	1482	K100578HD
68 7/8	1750	K080683HD	98 1/4	2496	K080976HD	58 1/2	1487	K100579HD
69 1/8	1756	K080685HD	99 1/8	2519	K080986HD	58 3/4	1492	K100582HD
69 5/8	1767	K080690HD	99 5/8	2531	K080991HD	59 1/4	1505	K100586HD
70	1777	K080694HD	100	2540	K080994HD	60	1523	K100594HD
70 1/2	1789	K080700HD	100 5/8	2555	K081000HD	60 1/2	1538	K100600HD
70 3/4	1798	K080702HD	101 1/8	2568	K081005HD	60 7/8	1546	K100601HD
71 1/4	1811	K080708HD	102 1/8	2594	K081015HD	61 1/8	1550	K100604HD
71 1/2	1816	K080710HD	102 5/8	2605	K081020HD	61 1/4	1557	K100607HD
71 3/4	1822	K080712HD	102 7/8	2613	K081023HD	61 5/8	1564	K100610HD
72 1/8	1831	K080716HD	103 1/8	2619	K081025HD	61 7/8	1572	K100613HD
72 3/8	1839	K080718HD	103 3/4	2635	K081032HD	62	1576	K100615HD
72 5/8	1845	K080720HD	104	2642	K081035HD	62 3/8	1585	K100618HD
72 7/8	1851	K080723HD	104 3/4	2660	K081040HD	63 5/8	1616	K100630HD
73 1/4	1859	K080726HD	105	2666	K081044HD	64 3/4	2153	K100635HD
73 1/2	1867	K080730HD	105 1/4	2673	K081047HD	64 1/4	1633	K100637HD
73 3/4	1874	K080733HD	105 3/4	2686	K081051HD	64 5/8	1642	K100640HD
74	1880	K080734HD	106 1/8	2694	K081055HD	65	1651	K100643HD
74 3/8	1889	K080738HD	106 1/2	2705	K081059HD	65 1/2	1664	K100649HD
74 5/8	1896	K080740HD	106 7/8	2715	K081062HD	66	1678	K100655HD
75 1/8	1907	K080745HD	107 1/8	2720	K081065HD	66 3/8	1687	K100658HD
75 5/8	1921	K080751HD	108	2745	K081074HD	66 3/4	1694	K100661HD
76	1931	K080755HD	108 1/2	2756	K081079HD	67 1/8	1704	K100665HD
76 1/2	1942	K080760HD	109 3/8	2778	K081088HD	67 1/2	1716	K100670HD
77	1957	K080765HD	109 3/4	2788	K081092HD	68	1728	K100675HD
77 1/2	1969	K080770HD	110 1/2	2807	K081099HD	68 1/4	1734	K100677HD
77 3/4	1976	K080774HD	110 3/4	2814	K081102HD	69 1/4	1758	K100686HD
78 1/8	1985	K080776HD	113	2869	K081124HD	70	1778	K100694HD
78 5/8	1996	K080780HD	113 3/4	2889	K081131HD	70 7/8	1800	K100702HD
79	2007	K080785HD	116 1/4	2953	K081153HD	71 1/4	1810	K100706HD
79 1/2	2019	K080790HD	118 1/4	3005	K081177HD	71 1/2	1816	K100710HD
79 5/8	2022	K080791HD	119 1/2	3034	K081189HD	72	1829	K100714HD
80	2032	K080794HD	120 1/8	3050	K081196HD	72 3/8	1840	K100719HD
80 1/8	2037	K080797HD	121 3/8	3082	K081207HD	72 5/8	1845	K100720HD
80 3/4	2050	K080801HD	121 7/8	3096	K081213HD	73 1/8	1859	K100726HD
81 1/8	2061	K080806HD	122 3/4	3117	K081223HD	73 5/8	1871	K100731HD
81 3/8	2067	K080808HD	124 7/8	3172	K081243HD	74 1/2	1893	K100739HD
81 5/8	2073	K080810HD	127	3227	K081264HD	75 1/8	1907	K100745HD
81 3/8	2080	K080813HD	127 1/8	3228	K081265HD	75 1/2	1918	K100749HD
82 1/8	2086	K080816HD	130 3/8	3312	K081298HD	76 3/4	1949	K100761HD
82 3/8	2091	K080817HD	131	3327	K081304HD	77	1957	K100764HD
82 3/4	2100	K080820HD	133 1/8	3381	K081325HD	77 3/4	1976	K100771HD
83 1/8	2112	K080825HD	133 3/4	3396	K081331HD	79 1/2	2019	K100789HD
83 3/4	2127	K080830HD	135 3/8	3439	K081348HD	81 5/8	2073	K100810HD
84	2134	K080834HD	136 1/2	3468	K081359HD	82	2083	K100814HD
84 3/8	2144	K080839HD	136 3/4	3474	K081362HD	82 1/8	2086	K100816HD
84 3/4	2154	K080842HD	137 1/2	3492	K081369HD	82 1/2	2096	K100818HD
85 1/8	2161	K080845HD	138 1/4	3513	K081377HD	82 3/4	2102	K100822HD
85 3/8	2175	K080850HD	<b>1 7/32" (31 mm) Top Width</b>			83 5/8	2124	K100830HD
85 3/4	2178	K080852HD	49 1/2	1258	K090490HD	85 7/8	2182	K100852HD
86 1/8	2187	K080855HD	50 1/2	1282	K090500HD	86 5/8	2200	K100860HD
86 3/8	2195	K080859HD	58 3/8	1482	K090578HD	87	2210	K100864HD
86 5/8	2200	K080860HD	59 1/4	1504	K090586HD			
87 1/8	2212	K080865HD						
87 3/8	2219	K080868HD						



# FLEETRUNNER® MICRO-V® BELTS – LISTED BY SIZE

Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>1 3/8" (35 mm) Top Width - Cont.</b>			<b>1 21/32" (42 mm) Top Width - Cont.</b>			<b>1 21/32" (42 mm) Top Width - Cont.</b>		
87 5/8	2226	K100870HD	56 1/2	1436	K120559HD	95	2415	K120945HD
88	2235	K100874HD	60	1523	K120594HD	97	2463	K120964HD
88 1/4	2242	K100877HD	61 1/8	1553	K120606HD	98 1/8	2492	K120975HD
88 1/2	2247	K100879HD	61 3/4	1569	K120610HD	98 1/2	2503	K120980HD
89	2261	K100884HD	64 5/8	1641	K120640HD	99 1/8	2516	K120985HD
89 1/8	2264	K100885HD	65	1651	K120645HD	99 7/8	2537	K120992HD
89 3/4	2278	K100891HD	67 5/32	1706	K120664HD	100 5/8	2556	K121000HD
90	2285	K100894HD	67 5/8	1718	K120671HD	104 1/2	2654	K121039HD
92 5/8	2354	K100921HD	70 3/4	1798	K120702HD	105 1/2	2680	K121049HD
94	2388	K100935HD	72 5/8	1845	K120720HD	113	2870	K121124HD
95 1/4	2419	K100946HD	73 1/2	1867	K120729HD	114 1/2	2909	K121139HD
95 5/8	2428	K100950HD	73 3/4	1873	K120732HD	<b>1 15/16" (49 mm) Top Width</b>		
95 7/8	2436	K100953HD	74	1880	K120734HD	28 1/2	723	K140279HD
96	2438	K100955HD	74 3/8	1889	K120738HD	35	890	K140345HD
98 1/4	2496	K100976HD	78	1982	K120774HD	37 1/2	954	K140370HD
98 7/8	2511	K100983HD	79	2007	K120784HD	43 1/2	1106	K140429HD
100	2539	K100994HD	79 1/8	2010	K120786HD	43 7/8	1116	K140433HD
100 3/8	2550	K100998HD	82	2083	K120815HD	45 5/8	1160	K140451HD
101 1/8	2569	K101005HD	83 1/8	2111	K120825HD	50 1/8	1274	K140496HD
101 1/2	2579	K101010HD	84 3/4	2154	K120842HD	52 1/8	1325	K140516HD
102	2591	K101015HD	85 3/4	2178	K120852HD	53 1/8	1350	K140524HD
107 1/8	2721	K101066HD	86 1/8	2188	K120855HD	56	1422	K140555HD
108 3/8	2753	K101078HD	86 3/8	2194	K120858HD	58 5/8	1490	K140580HD
109 5/8	2786	K101091HD	86 7/8	2208	K120864HD	60	1523	K140594HD
110 1/8	2797	K101096HD	87 1/4	2215	K120866HD	60 3/8	1534	K140597HD
112	2846	K101115HD	87 5/8	2225	K120870HD	60 7/8	1546	K140603HD
133 3/4	3397	K101331HD	87 3/4	2230	K120872HD	62 3/8	1585	K140618HD
<b>1 21/32" (42 mm) Top Width</b>			88 1/8	2239	K120876HD	63 3/8	1609	K140627HD
28 3/4	730	K120281HD	88 3/8	2245	K120878HD	66 3/4	1696	K140662HD
36 5/8	929	K120360HD	89 5/8	2278	K120891HD	68 3/4	1746	K140682HD
39 3/4	1008	K120390HD	90 1/8	2289	K120895HD	70 1/2	1789	K140700HD
40 3/4	1034	K120400HD	90 5/8	2301	K120901HD	<b>2 1/16" (53 mm) Top Width</b>		
41 1/2	1054	K120410HD	90 7/8	2308	K120903HD	68 5/8	1743	K150680HD
46 1/4	1175	K120457HD	91 1/8	2315	K120905HD	73 1/2	1867	K150730HD
46 7/8	1191	K120463HD	91 5/8	2326	K120910HD			
48 1/4	1226	K120476HD	91 3/4	2329	K120911HD			
48 7/8	1241	K120483HD	92 1/8	2340	K120915HD			
53 1/8	1351	K120525HD	92 1/2	2350	K120919HD			
			93 1/8	2364	K120924HD			
			93 3/4	2381	K120931HD			



## Showing Belt Numbers with Corresponding Nominal Outside Lengths and Top Widths

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
2PJ800	31 7/8	810	3/16	4.7	K030350	35 5/8	906	13/32	11
2PJ836	33 1/4	846	3/16	4.7	K030365	37 1/8	943	13/32	11
2PJ845	33 5/8	855	3/16	4.7	K030384	39 1/8	993	13/32	11
2PJ860	34 1/4	870	3/16	4.7	K030390	39 5/8	1006	13/32	11
2PJ905	36	915	3/16	4.7	K030395	40 1/8	1019	13/32	11
6PK1190	46 27/32	1190	13/16	21	K030415	42	1067	13/32	11
6PK1660	65 1/2	1660	13/16	21	K030425	43 1/8	1095	13/32	11
6PK1856	73	1856	13/16	21	K030441	44 5/8	1133	13/32	11
6PK1880	74 7/16	1877	13/16	21	K030455	46	1168	13/32	11
6PK1882	73 7/8	1882	13/16	21	K030471	47 3/4	1212	13/32	11
6PK1890	74 13/32	1890	13/16	21	K040220	22 3/4	578	9/16	14
6PK2090	82 3/8	2090	13/16	21	K040233	24 1/2	622	9/16	14
7PK1930	76	1930	15/16	24	K040245	25 1/4	640	9/16	14
7PK2164	85 1/8	2164	15/16	24	K040250	25 3/4	654	9/16	14
7PK2217	87 9/32	2217	15/16	24	K040270	27 3/4	704	9/16	14
DK050565	* 57 3/4	1468	21/32	17	K040274	28	710	9/16	14
DK050610	* 62 1/8	1579	21/32	17	K040275	28 1/4	718	9/16	14
DK060472	* 48 1/2	1232	13/16	20	K040285	29 1/4	743	9/16	14
DK060504	* 51	1295	13/16	20	K040292	29 3/4	756	9/16	14
DK060519	* 53	1348	13/16	20	K040300	30 3/4	781	9/16	14
DK060650	* 66 1/8	1680	13/16	20	K040305	31 1/4	793	9/16	14
DK060674	* 68 1/2	1741	13/16	20	K040310	31 5/8	803	9/16	14
DK060702	* 71 1/4	1811	13/16	20	K040315	32 1/4	818	9/16	14
DK060718	* 73	1853	13/16	20	K040319	32 1/2	826	9/16	14
DK060725	* 73 3/4	1872	13/16	20	K040320	32 3/4	831	9/16	14
DK060729	* 74 1/4	1885	13/16	20	K040322	32 7/8	835	9/16	14
DK060791	* 80 3/8	2043	13/16	20	K040325	33 1/4	845	9/16	14
DK060809	* 82	2083	13/16	20	K040329	33 3/8	849	9/16	14
DK060859	* 87 1/8	2213	13/16	20	K040330	33 5/8	854	9/16	14
DK060867	* 87 7/8	2232	13/16	20	K040332	33 3/4	857	9/16	14
DK060901	* 90 5/8	2302	13/16	20	K040335	34	864	9/16	14
DK060956	* 95 3/4	2432	13/16	20	K040336	34 1/8	867	9/16	14
DK060973	* 98 5/8	2504	13/16	20	K040337	34 1/4	871	9/16	14
DK070536	* 54 7/8	1394	15/16	24	K040338	34 3/8	874	9/16	14
DK070551	* 56 3/8	1432	15/16	24	K040340	34 5/8	879	9/16	14
DK070817	* 82 7/8	2105	15/16	24	K040343	34 7/8	885	9/16	14
DK071135	* 114 1/8	2899	15/16	24	K040345	35	889	9/16	14
DK080522	* 53 3/8	1356	1 3/32	28	K040346	35 1/4	894	9/16	14
DK080534	* 54	1370	1 3/32	28	K040347	35 1/4	895	9/16	14
DK080555	* 56 5/8	1438	1 3/32	28	K040350	35 5/8	906	9/16	14
DK080562	* 57 1/2	1462	1 3/32	28	K040353	35 7/8	912	9/16	14
DK080566	* 57 7/8	1470	1 3/32	28	K040355	36 1/8	918	9/16	14
DK080568	* 57 3/8	1457	1 3/32	28	K040358	36 3/8	924	9/16	14
DK081254	* 126	3200	1 3/32	28	K040360	36 3/4	933	9/16	14
DK081396	* 140 3/4	3575	1 3/32	28	K040365	37 1/8	943	9/16	14
DK081403	* 140 7/8	3579	1 3/32	28	K040367	37 3/8	949	9/16	14
DK100672	* 68 3/8	1737	1 3/8	35	K040370	37 1/2	953	9/16	14
DK100743	* 75 3/8	1915	1 3/8	35	K040372	38	964	9/16	14
DK100744	* 75	1905	1 3/8	35	K040378	38 1/2	978	9/16	14
K030195	20	509	13/32	11	K040382	38 3/4	983	9/16	14
K030220	22 5/8	576	13/32	11	K040384	39	991	9/16	14
K030231	23 3/4	603	13/32	11	K040385	39 1/8	993	9/16	14
K030236	24 1/4	615	13/32	11	K040388	39 3/8	999	9/16	14
K030240	24 3/4	629	13/32	11	K040390	39 5/8	1008	9/16	14
K030243	24 7/8	632	13/32	11	K040395	40 1/4	1021	9/16	14
K030245	25 1/4	640	13/32	11	K040398	40 3/8	1027	9/16	14
K030250	25 3/4	654	13/32	11	K040399	40 5/8	1031	9/16	14
K030265	27 1/8	689	13/32	11	K040400	40 5/8	1032	9/16	14
K030267	27 3/8	695	13/32	11	K040405	41 1/4	1047	9/16	14
K030267A	+ 27 1/4	692	13/32	11	K040410	41 5/8	1057	9/16	14
K030273	27 7/8	708	13/32	11	K040413	42	1067	9/16	14
K030280	28 3/4	730	13/32	11	K040415	42	1068	9/16	14
K030284	28 7/8	733	13/32	11	K040418	42 3/8	1076	9/16	14
K030290	29 3/4	755	13/32	11	K040420	42 5/8	1084	9/16	14
K030295	30 1/8	765	13/32	11	K040423	42 7/8	1089	9/16	14
K030299	30 1/2	775	13/32	11	K040425	43 1/8	1095	9/16	14
K030300	30 3/4	781	13/32	11	K040430	43 3/4	1111	9/16	14
K030310	31 5/8	803	13/32	11	K040438	44 3/8	1128	9/16	14
K030316	32 1/8	816	13/32	11	K040440	44 5/8	1133	9/16	14
K030323	32 7/8	836	13/32	11	K040445	45 1/8	1148	9/16	14
K030328	33 1/2	851	13/32	11	K040450	45 5/8	1160	9/16	14
K030334	34	864	13/32	11	K040457	46 1/4	1175	9/16	14
K030338	34 3/8	874	13/32	11	K040460	46 5/8	1184	9/16	14
K030340	34 5/8	879	13/32	11	K040465	47	1195	9/16	14
K030342	34 7/8	886	13/32	11	K040466	47 1/4	1200	9/16	14

\* Dual Side Belt    + Aramid Cord

Size Lists



# MICRO-V® BELTS – LISTED BY NUMBER

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
K040470	47 5/8	1210	9/16	14	K050450	45 5/8	1160	21/32	17
K040476	48 1/8	1223	9/16	14	K050455	46	1170	21/32	17
K040488	49 3/8	1255	9/16	14	K050459	46 3/8	1179	21/32	17
K040488A	+ 49 3/8	1254	9/16	14	K050460	46 5/8	1186	21/32	17
K040490	49 1/2	1258	9/16	14	K050470	47 5/8	1210	21/32	17
K040500	50 5/8	1286	9/16	14	K050474	47 7/8	1218	21/32	17
K040506	51 1/8	1299	9/16	14	K050478	48 3/8	1228	21/32	17
K040510	51 1/2	1309	9/16	14	K050480	48 5/8	1237	21/32	17
K040512	51 3/4	1315	9/16	14	K050486	49 1/8	1248	21/32	17
K040514	52	1320	9/16	14	K050490	49 1/2	1258	21/32	17
K040517	52 1/8	1325	9/16	14	K050500	50 5/8	1286	21/32	17
K040520	52 5/8	1338	9/16	14	K050505	51	1295	21/32	17
K040525	53 1/8	1351	9/16	14	K050507	51 1/8	1299	21/32	17
K040529	53 1/2	1359	9/16	14	K050510	51 3/4	1314	21/32	17
K040533	53 7/8	1368	9/16	14	K050516	52 1/4	1327	21/32	17
K040535	54	1373	9/16	14	K050520	52 5/8	1338	21/32	17
K040539	54 1/2	1385	9/16	14	K050523	52 7/8	1343	21/32	17
K040545	55 1/8	1399	9/16	14	K050530	53 1/2	1359	21/32	17
K040551	55 3/4	1415	9/16	14	K050532	53 7/8	1367	21/32	17
K040560	56 1/2	1435	9/16	14	K050538	54 3/8	1380	21/32	17
K040570	57 5/8	1464	9/16	14	K050545	55 1/4	1404	21/32	17
K040575	58 1/8	1475	9/16	14	K050551	55 3/4	1415	21/32	17
K040595	60	1523	9/16	14	K050565	57	1448	21/32	17
K040620	62 5/8	1591	9/16	14	K050570	57 1/2	1462	21/32	17
K040630	63 5/8	1615	9/16	14	K050586	59 1/4	1504	21/32	17
K040635	64	1626	9/16	14	K050594	60	1524	21/32	17
K040685	69 1/8	1756	9/16	14	K050609	61 1/2	1563	21/32	17
K040745	75 1/8	1907	9/16	14	K050612	61 3/4	1568	21/32	17
K040762	76 3/4	1950	9/16	14	K050618	62 3/8	1584	21/32	17
K040882	88 3/4	2255	9/16	14	K050625	63 1/8	1603	21/32	17
K040940	94 5/8	2403	9/16	14	K050630	63 5/8	1616	21/32	17
K050200	20 3/4	527	21/32	17	K050635	64 1/8	1627	21/32	17
K050271	27 3/4	704	21/32	17	K050640	64 5/8	1642	21/32	17
K050275	28 1/4	717	21/32	17	K050644	65	1651	21/32	17
K050280	28 3/4	730	21/32	17	K050647	65 1/4	1657	21/32	17
K050290	29 3/4	755	21/32	17	K050650	65 5/8	1667	21/32	17
K050316	32 1/4	819	21/32	17	K050653	65 7/8	1675	21/32	17
K050317	32 1/2	826	21/32	17	K050655	66 1/8	1680	21/32	17
K050321	32 3/4	831	21/32	17	K050658	66 3/8	1687	21/32	17
K050323	32 7/8	835	21/32	17	K050660	66 3/4	1696	21/32	17
K050326	33 1/4	843	21/32	17	K050665	67 1/8	1704	21/32	17
K050330	33 5/8	854	21/32	17	K050685	69	1753	21/32	17
K050335	34	864	21/32	17	K050689	69 5/8	1768	21/32	17
K050336	34 1/4	871	21/32	17	K050690	69 3/4	1772	21/32	17
K050339	34 1/2	876	21/32	17	K050694	70	1778	21/32	17
K050340	34 5/8	880	21/32	17	K050705	71 1/8	1807	21/32	17
K050344	35	889	21/32	17	K050715	72 1/8	1831	21/32	17
K050345	35 1/4	895	21/32	17	K050720	72 5/8	1845	21/32	17
K050350	35 5/8	905	21/32	17	K050744	75	1905	21/32	17
K050355	36 1/8	918	21/32	17	K050750	75 3/8	1914	21/32	17
K050358	36 3/8	924	21/32	17	K050755	76	1932	21/32	17
K050360	36 3/4	932	21/32	17	K050757	76 1/4	1937	21/32	17
K050364	37	939	21/32	17	K050778	78 3/8	1989	21/32	17
K050365	37 1/8	943	21/32	17	K050780	78 1/2	1994	21/32	17
K050368	37 3/8	949	21/32	17	K050817	82 1/2	2096	21/32	17
K050370	37 5/8	956	21/32	17	K050825	83 1/8	2112	21/32	17
K050375	38 1/4	972	21/32	17	K050835	84	2134	21/32	17
K050380	38 5/8	981	21/32	17	K050836	84 1/8	2138	21/32	17
K050385	39 1/8	994	21/32	17	K050845	85 1/8	2164	21/32	17
K050390	39 5/8	1006	21/32	17	K050855	86 1/8	2187	21/32	17
K050396	40 1/4	1021	21/32	17	K050887	89 1/8	2265	21/32	17
K050398	40 3/8	1027	21/32	17	K060288	29 1/2	749	13/16	20
K050400	40 5/8	1032	21/32	17	K060295	30 1/8	765	13/16	20
K050402	40 3/4	1035	21/32	17	K060305	31 1/4	793	13/16	20
K050404	41	1041	21/32	17	K060325	33 1/4	845	13/16	20
K050405	41 1/4	1048	21/32	17	K060331	33 5/8	854	13/16	20
K050407	41 3/8	1050	21/32	17	K060338	34 3/8	873	13/16	20
K050410	41 5/8	1058	21/32	17	K060340	34 3/4	881	13/16	20
K050415	42	1068	21/32	17	K060345	35 1/4	895	13/16	20
K050418	42 3/8	1076	21/32	17	K060352	35 7/8	911	13/16	20
K050420	42 5/8	1083	21/32	17	K060355	36 1/8	918	13/16	20
K050425	43 1/8	1094	21/32	17	K060365	37 1/8	943	13/16	20
K050429	43 3/8	1102	21/32	17	K060370	37 5/8	957	13/16	20
K050430	43 5/8	1108	21/32	17	K060374	37 7/8	963	13/16	20
K050433	43 3/4	1111	21/32	17	K060376	38 1/8	968	13/16	20
K050435	44 1/8	1121	21/32	17	K060378	38 3/8	975	13/16	20
K050438	44 1/2	1129	21/32	17	K060380	38 5/8	981	13/16	20
K050440	44 5/8	1135	21/32	17	K060385	39 1/8	993	13/16	20
K050442	44 3/4	1137	21/32	17	K060388	39 3/8	999	13/16	20
K050446	45 1/8	1148	21/32	17	K060390	39 3/4	1008	13/16	20
K050448	45 3/8	1153	21/32	17	K060393	39 7/8	1012	13/16	20

+ Aramid Cord

# MICRO-V® BELTS – LISTED BY NUMBER



Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
K060394	40	1016	13/16	20	K060609	61 1/2	1563	13/16	20
K060396A	+ 40 1/4	1022	13/16	20	K060612	61 3/4	1569	13/16	20
K060400	40 3/4	1034	13/16	20	K060615	62 1/8	1577	13/16	20
K060405	41	1042	13/16	20	K060620	62 5/8	1591	13/16	20
K060406	41 1/4	1050	13/16	20	K060623	62 7/8	1598	13/16	20
K060407	41 3/8	1051	13/16	20	K060625	63 1/8	1603	13/16	20
K060408	41 1/2	1054	13/16	20	K060628	63 3/8	1610	13/16	20
K060409	41 1/2	1054	13/16	20	K060630	63 5/8	1616	13/16	20
K060410	41 5/8	1058	13/16	20	K060631	63 3/4	1619	13/16	20
K060415	42	1067	13/16	20	K060635	64 1/8	1627	13/16	20
K060418	42 3/8	1076	13/16	20	K060637	64 3/8	1634	13/16	20
K060420	42 1/2	1080	13/16	20	K060640	64 5/8	1641	13/16	20
K060423	42 7/8	1089	13/16	20	K060642	64 3/4	1646	13/16	20
K060425	43 1/8	1095	13/16	20	K060645	65	1651	13/16	20
K060426	43 1/8	1096	13/16	20	K060650	65 1/2	1665	13/16	20
K060427	43 3/8	1102	13/16	20	K060651	65 3/4	1670	13/16	20
K060431	43 3/4	1111	13/16	20	K060653	65 7/8	1674	13/16	20
K060434	43 7/8	1116	13/16	20	K060658	66 3/8	1687	13/16	20
K060435	44 1/8	1122	13/16	20	K060660	66 3/4	1696	13/16	20
K060439	44 3/8	1127	13/16	20	K060663	66 7/8	1699	13/16	20
K060441	44 5/8	1135	13/16	20	K060664A	+ 66 7/8	1699	13/16	20
K060445	45 1/8	1148	13/16	20	K060667	67 1/4	1708	13/16	20
K060448	45 3/8	1153	13/16	20	K060670	67 1/2	1716	13/16	20
K060450	45 5/8	1160	13/16	20	K060672	67 3/4	1722	13/16	20
K060455	46	1170	13/16	20	K060675	68	1728	13/16	20
K060456	46 1/4	1175	13/16	20	K060680	68 5/8	1742	13/16	20
K060458	46 3/8	1179	13/16	20	K060682	68 7/8	1750	13/16	20
K060461	46 5/8	1186	13/16	20	K060685	69 1/8	1756	13/16	20
K060465	47	1195	13/16	20	K060690	69 5/8	1767	13/16	20
K060468	47 3/8	1204	13/16	20	K060695	70	1777	13/16	20
K060469A	+ 47 1/2	1207	13/16	20	K060696	70 1/4	1783	13/16	20
K060470	47 5/8	1211	13/16	20	K060700	70 5/8	1794	13/16	20
K060473	47 7/8	1216	13/16	20	K060703	70 7/8	1799	13/16	20
K060473A	+ 48	1219	13/16	20	K060705	71 1/8	1807	13/16	20
K060474	47 7/8	1217	13/16	20	K060710	71 1/2	1816	13/16	20
K060478	48 1/4	1227	13/16	20	K060711	71 5/8	1820	13/16	20
K060480	48 5/8	1235	13/16	20	K060711A	+ 71 3/4	1822	13/16	20
K060480A	+ 48 1/2	1232	13/16	20	K060714	72	1829	13/16	20
K060483	48 7/8	1241	13/16	20	K060716	72	1830	13/16	20
K060486	49 1/8	1248	13/16	20	K060721	72 5/8	1845	13/16	20
K060490	49 1/2	1258	13/16	20	K060722	72 3/4	1848	13/16	20
K060492	49 3/4	1265	13/16	20	K060724	73	1854	13/16	20
K060494	50	1270	13/16	20	K060725	73 1/4	1859	13/16	20
K060495	50 1/8	1274	13/16	20	K060726A	+ 73 1/8	1857	13/16	20
K060499	50 1/2	1283	13/16	20	K060730	73 1/2	1867	13/16	20
K060500	50 3/4	1288	13/16	20	K060733	73 7/8	1876	13/16	20
K060505	51	1297	13/16	20	K060735	74 1/8	1881	13/16	20
K060507	51 1/8	1300	13/16	20	K060739	74 1/2	1893	13/16	20
K060509	51 1/2	1309	13/16	20	K060744	75	1904	13/16	20
K060512	51 3/4	1314	13/16	20	K060747	75 3/8	1914	13/16	20
K060514	52	1321	13/16	20	K060750	75 5/8	1921	13/16	20
K060516	52 1/8	1325	13/16	20	K060751	75 3/4	1924	13/16	20
K060520	52 3/4	1339	13/16	20	K060755	76	1932	13/16	20
K060523	52 7/8	1343	13/16	20	K060760	76 1/2	1942	13/16	20
K060525	53 3/8	1356	13/16	20	K060763	76 7/8	1951	13/16	20
K060529	53 1/2	1359	13/16	20	K060764	77	1957	13/16	20
K060532	53 7/8	1367	13/16	20	K060766A	+ 77 1/4	1962	13/16	20
K060535	54 1/4	1379	13/16	20	K060770	77 3/8	1967	13/16	20
K060539	54 1/2	1385	13/16	20	K060771	77 5/8	1971	13/16	20
K060544	55	1397	13/16	20	K060772	77 7/8	1977	13/16	20
K060547	55 1/4	1404	13/16	20	K060775	78	1982	13/16	20
K060551	55 3/4	1415	13/16	20	K060776	78 1/4	1988	13/16	20
K060555	56	1423	13/16	20	K060780	78 5/8	1996	13/16	20
K060557	56 1/4	1429	13/16	20	K060785	79	2007	13/16	20
K060559	56 1/2	1436	13/16	20	K060787	79 1/8	2010	13/16	20
K060560	56 5/8	1439	13/16	20	K060790	79 1/2	2018	13/16	20
K060563	56 7/8	1445	13/16	20	K060792	79 3/4	2026	13/16	20
K060563A	+ 56 3/4	1441	13/16	20	K060795	80 1/8	2034	13/16	20
K060569	57 1/2	1462	13/16	20	K060798	80 3/8	2040	13/16	20
K060573	57 7/8	1471	13/16	20	K060802	80 3/4	2051	13/16	20
K060575	58	1473	13/16	20	K060804	81	2057	13/16	20
K060578	58 3/8	1483	13/16	20	K060806	81 1/8	2061	13/16	20
K060583	58 3/4	1492	13/16	20	K060810	81 5/8	2073	13/16	20
K060586	59 1/4	1504	13/16	20	K060812	81 3/4	2076	13/16	20
K060588	59 3/8	1508	13/16	20	K060815	82 1/8	2085	13/16	20
K060591	59 5/8	1515	13/16	20	K060819	82 1/2	2093	13/16	20
K060594	60	1523	13/16	20	K060820	82 1/2	2096	13/16	20
K060598	60 3/8	1534	13/16	20	K060822	82 3/4	2102	13/16	20
K060602	60 3/4	1542	13/16	20	K060824	83	2108	13/16	20
K060604	60 7/8	1547	13/16	20	K060825	83 1/8	2112	13/16	20
K060605	61 1/8	1553	13/16	20	K060827	83 1/4	2116	13/16	20

+ Aramid Cord





# MICRO-V® BELTS – LISTED BY NUMBER

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
K060827A	+ 83 3/8	2118	13/16	20	K060997	100 1/4	2546	13/16	20
K060828	83 3/8	2119	13/16	20	K061000	100 5/8	2555	13/16	20
K060832	83 3/4	2127	13/16	20	K061002	100 3/4	2559	13/16	20
K060834	84	2134	13/16	20	K061005	101 1/8	2568	13/16	20
K060834A	+ 84	2134	13/16	20	K061010	101 5/8	2581	13/16	20
K060837	84 1/4	2140	13/16	20	K061015	102 1/8	2593	13/16	20
K060837A	+ 84 1/4	2140	13/16	20	K061016	102 1/4	2596	13/16	20
K060840	84 1/2	2146	13/16	20	K061020	102 5/8	2605	13/16	20
K060840A	+ 84 1/2	2146	13/16	20	K061025	103	2615	13/16	20
K060841	84 5/8	2149	13/16	20	K061031	103 5/8	2633	13/16	20
K060842	84 3/4	2153	13/16	20	K061033	103 7/8	2639	13/16	20
K060845	85 1/4	2165	13/16	20	K061037	104 1/4	2649	13/16	20
K060849	85 1/2	2171	13/16	20	K061045	105	2666	13/16	20
K060850	85 5/8	2175	13/16	20	K061049	105 1/2	2680	13/16	20
K060851A	+ 85 5/8	2175	13/16	20	K061054	106	2692	13/16	20
K060854	85 7/8	2182	13/16	20	K061058	106 3/8	2701	13/16	20
K060854A	+ 85 7/8	2182	13/16	20	K061062	106 3/4	2711	13/16	20
K060858	86 3/8	2193	13/16	20	K061066	107 1/8	2722	13/16	20
K060860	86 5/8	2201	13/16	20	K061073	107 7/8	2741	13/16	20
K060861A	+ 86 5/8	2200	13/16	20	K061075	108 1/8	2746	13/16	20
K060863	86 7/8	2206	13/16	20	K061077	108 1/4	2750	13/16	20
K060864	86 7/8	2208	13/16	20	K061080	108 3/4	2761	13/16	20
K060866	87 1/4	2216	13/16	20	K061093	109 3/4	2788	13/16	20
K060867A	+ 87 1/4	2216	13/16	20	K061098	109 3/8	2780	13/16	20
K060868	87 3/8	2219	13/16	20	K061099	110 1/2	2807	13/16	20
K060870	87 5/8	2225	13/16	20	K061102	110 3/4	2814	13/16	20
K060873A	+ 87 7/8	2232	13/16	20	K061105	111 1/8	2824	13/16	20
K060874	87 7/8	2233	13/16	20	K061110	111 5/8	2835	13/16	20
K060874A	+ 88	2235	13/16	20	K061115	111 7/8	2841	13/16	20
K060875	88 1/8	2238	13/16	20	K061120	112 1/2	2859	13/16	20
K060876	88 1/8	2239	13/16	20	K061123	112 7/8	2869	13/16	20
K060878	88 3/8	2245	13/16	20	K061130	113 5/8	2886	13/16	20
K060880A	+ 88 1/2	2248	13/16	20	K061140	114 1/2	2910	13/16	20
K060882	88 7/8	2257	13/16	20	K061141	114 5/8	2911	13/16	20
K060883	89	2261	13/16	20	K061145	115 1/4	2927	13/16	20
K060885	89 1/8	2263	13/16	20	K061177	118 1/4	3005	13/16	20
K060885A	+ 89	2261	13/16	20	K061187	119 1/4	3030	13/16	20
K060886	89 1/8	2265	13/16	20	K061195	120 1/8	3051	13/16	20
K060888	89 1/2	2273	13/16	20	K061203	120 7/8	3069	13/16	20
K060891	89 3/4	2278	13/16	20	K061230	123 5/8	3137	13/16	20
K060893	89 7/8	2283	13/16	20	K061247	125 1/4	3183	13/16	20
K060893A	+ 89 7/8	2283	13/16	20	K061251	125 5/8	3192	13/16	20
K060895	90 1/8	2289	13/16	20	K061265	127	3226	13/16	20
K060895A	+ 90 1/8	2289	13/16	20	K061280	128 5/8	3267	13/16	20
K060900	90 5/8	2301	13/16	20	K061298	130 3/8	3312	13/16	20
K060905	90 7/8	2308	13/16	20	K061360	136 1/2	3467	13/16	20
K060905A	+ 90 7/8	2308	13/16	20	K061369	137 1/2	3492	13/16	20
K060908	91 1/4	2318	13/16	20	K061373	137 7/8	3502	13/16	20
K060908A	+ 91 1/4	2318	13/16	20	K061380	138 5/8	3519	13/16	20
K060910	91 5/8	2329	13/16	20	K061380A	+ 138 5/8	3521	13/16	20
K060911A	+ 91 3/4	2330	13/16	20	K061395A	+ 139 9/16	3559	13/16	20
K060913	92	2337	13/16	20	K061420	142 1/2	3621	13/16	20
K060915	92 1/8	2340	13/16	20	K061490	149 1/2	3799	13/16	20
K060916A	+ 92 1/8	2340	13/16	20	K070319	32 1/2	826	15/16	24
K060919	92 3/8	2346	13/16	20	K070362	36 7/8	935	15/16	24
K060919A	+ 92 3/8	2346	13/16	20	K070365EMD	■ 37 1/8	943	15/16	24
K060923	92 7/8	2360	13/16	20	K070370	37 3/4	957	15/16	24
K060926	93 1/8	2364	13/16	20	K070381	38 5/8	981	15/16	24
K060928	93 1/4	2369	13/16	20	K070381EMD	■ 38 5/8	981	15/16	24
K060930	93 5/8	2377	13/16	20	K070390	39 3/4	1008	15/16	24
K060935	94	2387	13/16	20	K070407	41 1/4	1048	15/16	24
K060938	94 1/2	2400	13/16	20	K070407A	+ 41 1/4	1048	15/16	24
K060942	94 3/4	2407	13/16	20	K070415	42	1068	15/16	24
K060945	95 1/8	2415	13/16	20	K070415EMD	■ 42	1068	15/16	24
K060947	95 1/4	2419	13/16	20	K070425	43 1/8	1095	15/16	24
K060950	95 5/8	2428	13/16	20	K070443	44 7/8	1140	15/16	24
K060952	95 3/4	2432	13/16	20	K070448	45 3/8	1153	15/16	24
K060956	96 1/8	2440	13/16	20	K070491EMD	■ 49 5/8	1261	15/16	24
K060960	96 5/8	2453	13/16	20	K070500	50 5/8	1286	15/16	24
K060962	96 7/8	2460	13/16	20	K070505	51 1/8	1300	15/16	24
K060966	97 1/8	2468	13/16	20	K070508	51 3/8	1305	15/16	24
K060970	97 5/8	2479	13/16	20	K070508EMD	■ 51 3/8	1305	15/16	24
K060975	98 1/8	2492	13/16	20	K070539	54 1/2	1385	15/16	24
K060980	98 5/8	2505	13/16	20	K070542	54 3/4	1391	15/16	24
K060984	99	2513	13/16	20	K070553	55 7/8	1418	15/16	24
K060986	99 1/4	2520	13/16	20	K070563	56 7/8	1445	15/16	24
K060988	99 1/2	2526	13/16	20	K070565	57	1448	15/16	24
K060990	99 5/8	2531	13/16	20	K070566	57 1/4	1454	15/16	24
K060994	99 7/8	2537	13/16	20	K070578	58 3/8	1483	15/16	24
K060995	100	2539	13/16	20	K070610	61 5/8	1564	15/16	24

■ Electro-Mechanical Drive Belt + Aramid Cord

# MICRO-V® BELTS – LISTED BY NUMBER



Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
K070615	.62 1/8	1578	15/16	24	K080334	.34	864	1 3/32	28
K070622	.62 3/4	1594	15/16	24	K080360	.36 3/4	932	1 3/32	28
K070628	.63 3/8	1609	15/16	24	K080365	.37 1/8	943	1 3/32	28
K070630	.63 5/8	1616	15/16	24	K080370	.37 3/4	957	1 3/32	28
K070640	.64 5/8	1642	15/16	24	K080375	.38 1/8	968	1 3/32	28
K070644	.65	1651	15/16	24	K080382	.38 3/4	983	1 3/32	28
K070649	.66 1/2	1688	15/16	24	K080384	.39	990	1 3/32	28
K070653	.65 7/8	1675	15/16	24	K080390	.39 3/4	1008	1 3/32	28
K070655	.66	1678	15/16	24	K080392	.39 7/8	1014	1 3/32	28
K070663	.66 3/4	1695	15/16	24	K080400	.40 3/4	1034	1 3/32	28
K070667	.67 1/4	1708	15/16	24	K080408	.41 3/8	1051	1 3/32	28
K070669	.67 1/2	1716	15/16	24	K080415	.42 1/8	1069	1 3/32	28
K070673	.67 3/4	1722	15/16	24	K080424	.43	1091	1 3/32	28
K070677	.68 1/4	1734	15/16	24	K080427	.43 1/2	1103	1 3/32	28
K070680	.68 5/8	1743	15/16	24	K080435	.44 1/8	1122	1 3/32	28
K070683	.68 7/8	1750	15/16	24	K080450	.45 5/8	1160	1 3/32	28
K070685	.69 1/8	1756	15/16	24	K080455	.46	1170	1 3/32	28
K070690	.69 1/2	1767	15/16	24	K080458	.46 3/8	1179	1 3/32	28
K070694	.70	1779	15/16	24	K080465	.47	1195	1 3/32	28
K070701	.70 3/4	1796	15/16	24	K080471	.47 3/4	1211	1 3/32	28
K070705	.71 1/8	1807	15/16	24	K080485	.49 1/8	1249	1 3/32	28
K070709	.71 1/2	1816	15/16	24	K080491	.49 5/8	1260	1 3/32	28
K070714	.72	1829	15/16	24	K080496	.50 1/8	1274	1 3/32	28
K070721	.72 3/4	1847	15/16	24	K080505	.51	1297	1 3/32	28
K070730	.73 5/8	1870	15/16	24	K080507	.51 1/4	1302	1 3/32	28
K070733	.73 3/4	1874	15/16	24	K080510	.51 1/2	1309	1 3/32	28
K070735	.74 1/8	1883	15/16	24	K080514	.52	1320	1 3/32	28
K070750	.75 5/8	1920	15/16	24	K080515	.52 1/8	1324	1 3/32	28
K070755	.76 1/8	1933	15/16	24	K080522	.52 3/4	1340	1 3/32	28
K070763	.76 7/8	1951	15/16	24	K080525	.53 1/8	1351	1 3/32	28
K070776	.78	1982	15/16	24	K080530	.53 1/2	1359	1 3/32	28
K070786	.79 1/8	2011	15/16	24	K080537	.54 1/4	1379	1 3/32	28
K070795	.80	2033	15/16	24	K080545	.55 1/8	1399	1 3/32	28
K070801	.80 3/4	2051	15/16	24	K080547	.55 1/4	1403	1 3/32	28
K070810	.81 5/8	2073	15/16	24	K080550	.55 3/4	1415	1 3/32	28
K070810A	+ 81 1/2	2070	15/16	24	K080558	.56 1/4	1429	1 3/32	28
K070822	.82 3/4	2102	15/16	24	K080560	.56 5/8	1439	1 3/32	28
K070825	.83 1/8	2112	15/16	24	K080565	.57	1448	1 3/32	28
K070830	.83 5/8	2124	15/16	24	K080566	.57 1/8	1452	1 3/32	28
K070834	.84	2133	15/16	24	K080570	.57 1/2	1462	1 3/32	28
K070835	.84	2134	15/16	24	K080575	.58 1/8	1475	1 3/32	28
K070846	.85 1/4	2164	15/16	24	K080580	.58 5/8	1490	1 3/32	28
K070852	.85 3/4	2178	15/16	24	K080585	.59	1499	1 3/32	28
K070855	.86 1/8	2187	15/16	24	K080590	.59 1/2	1512	1 3/32	28
K070873	.87 7/8	2232	15/16	24	K080594	.60	1523	1 3/32	28
K070880	.88 1/2	2249	15/16	24	K080600	.60 5/8	1538	1 3/32	28
K070882	.88 3/4	2255	15/16	24	K080605	.61 1/8	1553	1 3/32	28
K070885	.89 1/8	2263	15/16	24	K080610	.61 3/4	1569	1 3/32	28
K070886	.89 1/8	2265	15/16	24	K080615	.62 1/8	1577	1 3/32	28
K070896	.90 1/8	2289	15/16	24	K080616	.62 1/4	1581	1 3/32	28
K070901	.90 5/8	2301	15/16	24	K080618	.62 3/8	1584	1 3/32	28
K070903	.90 7/8	2308	15/16	24	K080620	.62 5/8	1591	1 3/32	28
K070905	.91 1/8	2314	15/16	24	K080623	.62 7/8	1598	1 3/32	28
K070916	.92 1/4	2343	15/16	24	K080626	.63 1/8	1603	1 3/32	28
K070922	.92 3/4	2357	15/16	24	K080627	.63 1/2	1613	1 3/32	28
K070924	.93	2362	15/16	24	K080630	.63 5/8	1616	1 3/32	28
K070931	.93 5/8	2378	15/16	24	K080635	.64 1/4	1633	1 3/32	28
K070951	.95 3/4	2431	15/16	24	K080644	.65	1651	1 3/32	28
K070961	.96 3/4	2457	15/16	24	K080645	.65 1/4	1657	1 3/32	28
K070971	.97 3/4	2481	15/16	24	K080649	.65 1/2	1665	1 3/32	28
K070975	.97 3/4	2484	15/16	24	K080653	.65 7/8	1674	1 3/32	28
K070976	.98 1/8	2492	15/16	24	K080655	.66 1/4	1683	1 3/32	28
K071005	101 1/8	2568	15/16	24	K080660	.66 1/2	1691	1 3/32	28
K071009	101 3/8	2576	15/16	24	K080661A	+ 66 3/4	1695	1 3/32	28
K071013	101 7/8	2586	15/16	24	K080662	.66 3/4	1695	1 3/32	28
K071031	103 5/8	2633	15/16	24	K080665	.67 1/8	1705	1 3/32	28
K071037	104 1/4	2649	15/16	24	K080670	.67 1/2	1716	1 3/32	28
K071040	104 5/8	2656	15/16	24	K080672	.67 3/4	1722	1 3/32	28
K071045	105 1/8	2671	15/16	24	K080675	.68	1728	1 3/32	28
K071056	106 1/4	2699	15/16	24	K080677	.68 1/4	1734	1 3/32	28
K071065	107 1/8	2720	15/16	24	K080680	.68 5/8	1742	1 3/32	28
K071130	113 5/8	2886	15/16	24	K080685	.69 1/8	1756	1 3/32	28
K071134	114	2897	15/16	24	K080690	.69 5/8	1767	1 3/32	28
K071141	114 5/8	2912	15/16	24	K080694	.70	1777	1 3/32	28
K071150	115 5/8	2936	15/16	24	K080700	.70 1/2	1789	1 3/32	28
K071157	116 1/4	2953	15/16	24	K080702	.70 3/4	1798	1 3/32	28
K071194	119 7/8	3046	15/16	24	K080708	.71 1/4	1811	1 3/32	28
K071213	121 7/8	3096	15/16	24	K080710	.71 1/2	1816	1 3/32	28
K071247	125 3/8	3183	15/16	24	K080712	.71 3/4	1822	1 3/32	28
K080300	.30 3/4	781	1 3/32	28	K080716	.72 1/8	1831	1 3/32	28
K080330	.33 3/4	856	1 3/32	28	K080720	.72 5/8	1845	1 3/32	28

+ Aramid Cord



# MICRO-V® BELTS – LISTED BY NUMBER

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
K080726	73 1/4	1859	1 3/32	28	K081243	124 7/8	3172	1 3/32	28
K080730	73 1/2	1867	1 3/32	28	K081253	125 7/8	3198	1 3/32	28
K080733	73 3/4	1874	1 3/32	28	K081264	127	3227	1 3/32	28
K080734	74	1880	1 3/32	28	K081265	127 1/8	3228	1 3/32	28
K080738	74 3/8	1889	1 3/32	28	K081298	130 3/8	3312	1 3/32	28
K080740	74 5/8	1896	1 3/32	28	K081325	133 1/8	3381	1 3/32	28
K080745	75 1/8	1907	1 3/32	28	K081331	133 3/4	3396	1 3/32	28
K080751	75 5/8	1921	1 3/32	28	K081348	135 3/8	3439	1 3/32	28
K080755	76	1931	1 3/32	28	K081352	135 3/4	3448	1 3/32	28
K080760	76 1/2	1942	1 3/32	28	K081359	136 1/2	3468	1 3/32	28
K080765	77	1957	1 3/32	28	K081362	136 3/4	3474	1 3/32	28
K080774	77 3/4	1976	1 3/32	28	K081377	138 1/4	3513	1 3/32	28
K080776	78 1/8	1985	1 3/32	28	K081490	149 1/2	3799	1 3/32	28
K080780	78 5/8	1996	1 3/32	28	K090500	50 1/2	1282	1 7/32	31
K080785	79	2007	1 3/32	28	K090609	61 1/2	1562	1 7/32	31
K080790	79 1/2	2019	1 3/32	28	K100381	38 3/4	983	1 3/8	35
K080791	79 5/8	2022	1 3/32	28	K100437	44 1/4	1124	1 3/8	35
K080797	80 1/8	2037	1 3/32	28	K100445	45 1/8	1148	1 3/8	35
K080803	80 7/8	2054	1 3/32	28	K100456	46 1/8	1173	1 3/8	35
K080806	81 1/8	2061	1 3/32	28	K100465	47	1195	1 3/8	35
K080808	81 3/8	2067	1 3/32	28	K100467A	+ 47 1/4	1200	1 3/8	35
K080810	81 5/8	2073	1 3/32	28	K100485	48 7/8	1241	1 3/8	35
K080816	82 1/8	2086	1 3/32	28	K100495	50 1/8	1274	1 3/8	35
K080817	82 3/8	2091	1 3/32	28	K100502	50 3/4	1288	1 3/8	35
K080820	82 3/4	2100	1 3/32	28	K100510	51 1/2	1309	1 3/8	35
K080825	83 1/8	2112	1 3/32	28	K100535	54	1373	1 3/8	35
K080830	83 3/4	2127	1 3/32	28	K100540	54 1/2	1385	1 3/8	35
K080839	84 3/8	2144	1 3/32	28	K100554	56	1423	1 3/8	35
K080842	84 3/4	2154	1 3/32	28	K100563	56 7/8	1444	1 3/8	35
K080852	85 3/4	2178	1 3/32	28	K100570	57 1/2	1462	1 3/8	35
K080855	86 1/8	2187	1 3/32	28	K100572	57 7/8	1469	1 3/8	35
K080859	86 3/8	2195	1 3/32	28	K100575	58 1/8	1475	1 3/8	35
K080865	87 1/8	2212	1 3/32	28	K100579	58 1/2	1487	1 3/8	35
K080872	87 3/4	2230	1 3/32	28	K100586	59 1/4	1505	1 3/8	35
K080876	88 1/8	2240	1 3/32	28	K100594	60	1523	1 3/8	35
K080878	88 3/8	2245	1 3/32	28	K100601	60 7/8	1547	1 3/8	35
K080893	89 7/8	2282	1 3/32	28	K100607	61 1/4	1557	1 3/8	35
K080897	90 3/8	2295	1 3/32	28	K100610	61 5/8	1564	1 3/8	35
K080903	90 7/8	2308	1 3/32	28	K100613	61 7/8	1572	1 3/8	35
K080907	91 1/4	2318	1 3/32	28	K100618	62 3/8	1585	1 3/8	35
K080910	91 5/8	2326	1 3/32	28	K100630	63 5/8	1616	1 3/8	35
K080913	91 7/8	2334	1 3/32	28	K100635	64 3/4	2153	1 3/8	35
K080915	92 1/8	2340	1 3/32	28	K100637	64 1/4	1633	1 3/8	35
K080922	92 3/4	2355	1 3/32	28	K100640	64 5/8	1642	1 3/8	35
K080926	93 1/8	2367	1 3/32	28	K100655	66	1678	1 3/8	35
K080934	93 7/8	2384	1 3/32	28	K100658	66 3/8	1687	1 3/8	35
K080939	94 1/2	2400	1 3/32	28	K100665	67 1/8	1704	1 3/8	35
K080944	95	2412	1 3/32	28	K100670	67 1/2	1716	1 3/8	35
K080948	95 3/8	2424	1 3/32	28	K100675	68	1728	1 3/8	35
K080952	95 3/4	2432	1 3/32	28	K100677	68 1/4	1734	1 3/8	35
K080956	96 1/4	2444	1 3/32	28	K100694	70	1778	1 3/8	35
K080968	97 1/2	2475	1 3/32	28	K100710	71 1/2	1816	1 3/8	35
K080976	98 1/4	2496	1 3/32	28	K100719	72 3/8	1840	1 3/8	35
K080981	98 5/8	2505	1 3/32	28	K100731	73 5/8	1871	1 3/8	35
K080986	99 1/8	2519	1 3/32	28	K100739	74 1/2	1893	1 3/8	35
K080991	99 5/8	2531	1 3/32	28	K100749	75 1/2	1918	1 3/8	35
K081000	100 5/8	2555	1 3/32	28	K100771	77 3/4	1976	1 3/8	35
K081005	101 1/8	2568	1 3/32	28	K100789	79 1/2	2019	1 3/8	35
K081020	102 5/8	2605	1 3/32	28	K100810	81 5/8	2073	1 3/8	35
K081023	102 7/8	2613	1 3/32	28	K100816	82 1/8	2086	1 3/8	35
K081035	104	2642	1 3/32	28	K100840	84 5/8	2149	1 3/8	35
K081040	104 1/32	2661	1 3/32	28	K100852	85 7/8	2182	1 3/8	35
K081051	105 3/4	2686	1 3/32	28	K100864	87	2210	1 3/8	35
K081059	106 1/2	2705	1 3/32	28	K100884	89	2261	1 3/8	35
K081062	106 7/8	2715	1 3/32	28	K100886	89 1/8	2264	1 3/8	35
K081074	108	2745	1 3/32	28	K100891	89 3/4	2278	1 3/8	35
K081079	108 1/2	2756	1 3/32	28	K100921	92 5/8	2354	1 3/8	35
K081088	109 3/8	2778	1 3/32	28	K100938	94 5/8	2404	1 3/8	35
K081092	109 3/4	2788	1 3/32	28	K100955	96	2438	1 3/8	35
K081102	110 3/4	2814	1 3/32	28	K100976	98 1/8	2492	1 3/8	35
K081124	113	2869	1 3/32	28	K100998	100 3/8	2550	1 3/8	35
K081131	113 3/4	2889	1 3/32	28	K101005	101 1/8	2569	1 3/8	35
K081145	115 1/8	2924	1 3/32	28	K101078	108 3/8	2753	1 3/8	35
K081153	116 1/4	2953	1 3/32	28	K110841	84 3/4	2153	1 1/2	38
K081177	118 1/4	3005	1 3/32	28	K120281	28 3/4	730	1 21/32	42
K081181	118 5/8	3013	1 3/32	28	K120360	36 5/8	929	1 21/32	42
K081189	119 1/2	3035	1 3/32	28	K120390	39 3/4	1008	1 21/32	42
K081196	120 1/8	3050	1 3/32	28	K120400	40 3/4	1034	1 21/32	42
K081207	121 3/8	3082	1 3/32	28	K120410	41 1/2	1054	1 21/32	42
K081213	121 7/8	3096	1 3/32	28	K120457	46 1/4	1175	1 21/32	42
K081223	122 3/4	3117	1 3/32	28	K120463	46 7/8	1191	1 21/32	42

+ Aramid Cord

# MICRO-V® BELTS – LISTED BY NUMBER



Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
K120476	.48 1/4	1226	1 21/32	42	K120919	.92 1/2	2350	1 21/32	42
K120483	.48 7/8	1241	1 21/32	42	K120924	.93 1/8	2364	1 21/32	42
K120525	.53 1/8	1351	1 21/32	42	K120931	.93 3/4	2381	1 21/32	42
K120559	.56 1/2	1436	1 21/32	42	K120964	.97	2463	1 21/32	42
K120594	.60	1523	1 21/32	42	K120979	.98 1/8	2492	1 21/32	42
K120606	.61 1/8	1553	1 21/32	42	K121039	1.04 1/2	2654	1 21/32	42
K120610	.61 3/4	1569	1 21/32	42	K121124	.113	2870	1 21/32	42
K120664	.67 3/16	1707	1 21/32	42	K140345	.35	890	1 15/16	49
K120671	.67 5/8	1718	1 21/32	42	K140352	.35 7/8	910	1 15/16	49
K120702	.70 3/4	1798	1 21/32	42	K140370	.37 1/2	954	1 15/16	49
K120720	.72 5/8	1845	1 21/32	42	K140429	.43 1/2	1106	1 15/16	49
K120734	.74	1880	1 21/32	42	K140433	.43 7/8	1116	1 15/16	49
K120738	.74 3/8	1889	1 21/32	42	K140451	.45 5/8	1160	1 15/16	49
K120784	.79	2007	1 21/32	42	K140496	.50 1/8	1274	1 15/16	49
K120815	.82	2083	1 21/32	42	K140516	.52 1/8	1325	1 15/16	49
K120825	.83 1/8	2111	1 21/32	42	K140524	.53 1/8	1350	1 15/16	49
K120842	.84 3/4	2154	1 21/32	42	K140555	.56	1422	1 15/16	49
K120852	.85 3/4	2178	1 21/32	42	K140580	.58 5/8	1490	1 15/16	49
K120858	.86 3/8	2194	1 21/32	42	K140594	.60	1523	1 15/16	49
K120864	.86 7/8	2208	1 21/32	42	K140597	.60 3/8	1534	1 15/16	49
K120872	.87 3/4	2230	1 21/32	42	K140603	.60 7/8	1546	1 15/16	49
K120876	.88 1/8	2239	1 21/32	42	K140618	.62 3/8	1585	1 15/16	49
K120878	.88 3/8	2245	1 21/32	42	K140627	.63 3/8	1609	1 15/16	49
K120891	.89 5/8	2278	1 21/32	42	K140662	.66 3/4	1696	1 15/16	49
K120901	.90 5/8	2301	1 21/32	42	K140682	.68 3/4	1746	1 15/16	49
K120903	.90 7/8	2308	1 21/32	42	K140700	.70 1/2	1789	1 15/16	49
K120905	.91 1/8	2315	1 21/32	42	K141009A	+ 101 5/8	2582	1 15/16	49
K120911	.91 3/4	2329	1 21/32	42	K150759	.76 3/8	1942	2 1/16	53
K120915	.92 1/8	2340	1 21/32	42					

+ Aramid Cord





## Showing Nominal Belt Top Widths and Outside Lengths with Our Corresponding Belt Numbers

Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>3/16" (4.7 mm) Top Width</b>			<b>9/16" (14 mm) Top Width - Cont.</b>			<b>21/32" (17 mm) Top Width</b>		
31 7/8	810	2PJ800				20 3/4	527	K050200
33 1/4	846	2PJ836	35	889	K040345	27 3/4	704	K050271
33 5/8	855	2PJ845	35 1/4	894	K040346	28 1/4	717	K050275
34 1/4	870	2PJ860	35 1/4	895	K040347	28 3/4	730	K050280
36	915	2PJ905	35 5/8	906	K040350	29 3/4	755	K050290
<b>13/32" (11 mm) Top Width</b>			35 7/8	912	K040353	32 1/4	819	K050316
20	509	K030195	36 1/8	918	K040355	32 1/2	826	K050317
22 5/8	576	K030220	36 3/8	924	K040358	32 3/4	831	K050321
23 3/4	603	K030231	36 3/4	933	K040360	32 7/8	835	K050323
24 1/4	615	K030236	37 1/8	943	K040365	33 1/4	843	K050326
24 3/4	629	K030240	37 3/8	949	K040367	33 5/8	854	K050330
24 7/8	632	K030243	37 1/2	953	K040370	34	864	K050335
25 1/4	640	K030245	38	964	K040372	34 1/4	871	K050336
25 3/4	654	K030250	38 1/2	978	K040378	34 1/2	876	K050339
27 1/8	689	K030265	38 3/4	983	K040382	34 5/8	880	K050340
27 3/8	695	K030267	39	991	K040384	35	889	K050344
27 1/4	692	+ K030267A	39 1/8	993	K040385	35 1/4	895	K050345
27 7/8	708	K030273	39 3/8	999	K040388	35 5/8	905	K050350
28 3/4	730	K030280	39 5/8	1008	K040390	36 1/8	918	K050355
28 7/8	733	K030284	40 1/4	1021	K040395	36 3/8	924	K050358
29 3/4	755	K030290	40 3/8	1027	K040398	36 3/4	932	K050360
30 1/8	765	K030295	40 5/8	1031	K040399	37	939	K050364
30 1/2	775	K030299	40 5/8	1032	K040400	37 1/8	943	K050365
30 3/4	781	K030300	41 1/4	1047	K040405	37 3/8	949	K050368
31 5/8	803	K030310	41 5/8	1057	K040410	37 5/8	956	K050370
32 1/8	816	K030316	42	1067	K040413	38 1/4	972	K050375
32 7/8	836	K030323	42	1068	K040415	38 5/8	981	K050380
33 1/2	851	K030328	42 3/8	1076	K040418	39 1/8	994	K050385
34	864	K030334	42 5/8	1084	K040420	39 5/8	1006	K050390
34 3/8	874	K030338	42 7/8	1089	K040423	40 1/4	1021	K050396
34 5/8	879	K030340	43 1/8	1095	K040425	40 3/8	1027	K050398
34 7/8	886	K030342	43 3/4	1111	K040430	40 5/8	1032	K050400
35 5/8	906	K030350	44 3/8	1128	K040438	40 3/4	1035	K050402
37 1/8	943	K030365	44 5/8	1133	K040440	41	1041	K050404
39 1/8	993	K030384	45 1/8	1148	K040445	41 1/4	1048	K050405
39 5/8	1006	K030390	45 5/8	1160	K040450	41 3/8	1050	K050407
40 1/8	1019	K030395	46 1/4	1175	K040457	41 5/8	1058	K050410
42	1067	K030415	46 5/8	1184	K040460	42	1068	K050415
43 1/8	1095	K030425	47	1195	K040465	42 3/8	1076	K050418
44 5/8	1133	K030441	47 1/4	1200	K040466	42 5/8	1083	K050420
46	1168	K030455	47 5/8	1210	K040470	43 1/8	1094	K050425
47 3/4	1212	K030471	48 1/8	1223	K040476	43 3/8	1102	K050429
<b>9/16" (14 mm) Top Width</b>			49 3/8	1254	+ K040488A	43 5/8	1108	K050430
22 3/4	578	K040220	49 1/2	1258	K040490	43 3/4	1111	K050433
24 1/2	622	K040233	50 5/8	1286	K040500	44 1/8	1121	K050435
25 1/4	640	K040245	51 1/8	1299	K040506	44 1/2	1129	K050438
25 3/4	654	K040250	51 1/2	1309	K040510	44 5/8	1135	K050440
27 3/4	704	K040270	51 3/4	1315	K040512	44 3/4	1137	K050442
28	710	K040274	52	1320	K040514	45 1/8	1148	K050446
28 1/4	718	K040275	52 1/8	1325	K040517	45 3/8	1153	K050448
29 1/4	743	K040285	52 5/8	1338	K040520	45 5/8	1160	K050450
29 3/4	756	K040292	53 1/8	1351	K040525	46	1170	K050455
30 3/4	781	K040300	53 1/2	1359	K040529	46 3/8	1179	K050459
31 1/4	793	K040305	53 7/8	1368	K040533	46 5/8	1186	K050460
31 5/8	803	K040310	54	1373	K040535	47 5/8	1210	K050470
32 1/4	818	K040315	54 1/2	1385	K040539	47 7/8	1218	K050474
32 1/2	826	K040319	55 1/8	1399	K040545	48 3/8	1228	K050478
32 3/4	831	K040320	55 3/4	1415	K040551	48 5/8	1237	K050480
32 7/8	835	K040322	56 1/2	1435	K040560	49 1/8	1248	K050486
33 1/4	845	K040325	56 5/8	1464	K040570	49 1/2	1258	K050490
33 3/8	849	K040329	58 1/8	1475	K040575	50 5/8	1286	K050500
33 5/8	854	K040330	60	1523	K040595	51	1295	K050505
33 3/4	857	K040332	62 5/8	1591	K040620	51 1/8	1299	K050507
34	864	K040335	63 5/8	1615	K040630	51 3/4	1314	K050510
34 1/8	867	K040336	64	1626	K040635	52 1/4	1327	K050516
34 1/4	871	K040337	69 1/8	1756	K040685	52 5/8	1338	K050520
34 3/8	874	K040338	75 1/8	1907	K040745	52 7/8	1343	K050523
34 5/8	879	K040340	76 3/4	1950	K040762	53 1/2	1359	K050530
34 7/8	885	K040343	88 3/4	2255	K040882	53 7/8	1367	K050532
			94 5/8	2403	K040940	54 3/8	1380	K050538
						55 1/4	1404	K050545
						55 3/4	1415	K050551
						57	1448	K050565

+ Aramid Cord



MICRO-V® BELTS – LISTED BY SIZE



Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>21/32" (17 mm) Top Width - Cont.</b>			<b>13/16" (20 mm) Top Width - Cont.</b>			<b>13/16" (20 mm) Top Width - Cont.</b>		
57 1/2	1462	K050570	43 1/8	1096	K060426	63 5/8	1616	K060630
57 3/4	1468	* DK050565	43 3/8	1102	K060427	63 3/4	1619	K060631
59 1/4	1504	K050586	43 3/4	1111	K060431	64 1/8	1627	K060635
60	1524	K050594	43 7/8	1116	K060434	64 3/8	1634	K060637
61 1/2	1563	K050609	44 1/8	1122	K060435	64 5/8	1641	K060640
61 3/4	1568	K050612	44 3/8	1127	K060439	64 3/4	1646	K060642
62 1/8	1579	* DK050610	44 5/8	1135	K060441	65	1651	K060645
62 3/8	1584	K050618	45 1/8	1148	K060445	65 1/2	1665	K060650
63 1/8	1603	K050625	45 3/8	1153	K060448	65 3/4	1670	K060651
63 5/8	1616	K050630	45 5/8	1160	K060450	65 7/8	1674	K060653
64 1/8	1627	K050635	46	1170	K060455	66 1/8	1680	* DK060650
64 5/8	1642	K050640	46 1/4	1175	K060456	66 3/8	1687	K060658
65	1651	K050644	46 3/8	1179	K060458	66 3/4	1696	K060660
65 1/4	1657	K050647	46 5/8	1186	K060461	66 7/8	1699	K060663
65 5/8	1667	K050650	47	1195	K060465	66 7/8	1699	+ K060664A
65 7/8	1675	K050653	47 3/8	1204	K060468	67 1/4	1708	K060667
66 1/8	1680	K050655	47 1/2	1207	+ K060469A	67 1/2	1716	K060670
66 3/8	1687	K050658	47 5/8	1211	K060470	67 3/4	1722	K060672
66 3/4	1696	K050660	47 7/8	1216	K060473	68	1728	K060675
67 1/8	1704	K050665	47 7/8	1217	K060474	68 1/2	1741	* DK060674
69	1753	K050685	48	1219	+ K060473A	68 5/8	1742	K060680
69 5/8	1768	K050689	48 1/4	1227	K060478	68 7/8	1750	K060682
69 3/4	1772	K050690	48 1/2	1232	* DK060472	69 1/8	1756	K060685
70	1778	K050694	48 1/2	1232	+ K060480A	69 5/8	1767	K060690
71 1/8	1807	K050705	48 5/8	1235	K060480	70	1777	K060695
72 1/8	1831	K050715	48 7/8	1241	K060483	70 1/4	1783	K060696
72 5/8	1845	K050720	49 1/8	1248	K060486	70 5/8	1794	K060700
75	1905	K050744	49 1/2	1258	K060490	70 7/8	1799	K060703
75 3/8	1914	K050750	49 3/4	1265	K060492	71 1/8	1807	K060705
76	1932	K050755	50	1270	K060494	71 1/4	1811	* DK060702
76 1/4	1937	K050757	50 1/8	1274	K060495	71 1/2	1816	K060710
78 3/8	1989	K050778	50 1/2	1283	K060499	71 5/8	1820	K060711
78 1/2	1994	K050780	50 3/4	1288	K060500	71 3/4	1822	+ K060711A
82 1/2	2096	K050817	51	1295	* DK060504	72	1829	K060714
83 1/8	2112	K050825	51	1297	K060505	72	1830	K060716
84	2134	K050835	51 1/8	1300	K060507	72 5/8	1845	K060721
84 1/8	2138	K050836	51 1/2	1309	K060509	72 3/4	1848	K060722
85 1/8	2164	K050845	51 3/4	1314	K060512	73	1853	* DK060718
86 1/8	2187	K050855	52	1321	K060514	73	1854	K060724
89 1/8	2265	K050887	52 1/8	1325	K060516	73 1/8	1857	+ K060726A
<b>13/16" (20 mm) Top Width</b>			52 3/4	1339	K060520	73 1/4	1859	K060725
29 1/2	749	K060288	52 7/8	1343	K060523	73 1/2	1867	K060730
30 1/8	765	K060295	53	1348	* DK060519	73 3/4	1872	* DK060725
31 1/4	793	K060305	53 3/8	1356	K060525	73 7/8	1876	K060733
33 1/4	845	K060325	53 1/2	1359	K060529	74 1/8	1881	K060735
33 5/8	854	K060331	53 7/8	1367	K060532	74 1/4	1885	* DK060729
34 3/8	873	K060338	54 1/4	1379	K060535	74 1/2	1893	K060739
34 3/4	881	K060340	54 1/2	1385	K060539	75	1904	K060744
35 1/4	895	K060345	55	1397	K060544	75 3/8	1914	K060747
35 7/8	911	K060352	55 1/4	1404	K060547	75 5/8	1921	K060750
36 1/8	918	K060355	55 3/4	1415	K060551	75 3/4	1924	K060751
37 1/8	943	K060365	56	1423	K060555	76	1932	K060755
37 5/8	957	K060370	56 1/4	1429	K060557	76 1/2	1942	K060760
37 7/8	963	K060374	56 1/2	1436	K060559	76 7/8	1951	K060763
38 1/8	968	K060376	56 5/8	1439	K060560	77	1957	K060764
38 3/8	975	K060378	56 7/8	1445	K060563	77 1/4	1962	+ K060766A
38 5/8	981	K060380	56 3/4	1441	+ K060563A	77 3/8	1967	K060770
39 1/8	993	K060385	57 1/2	1462	K060569	77 5/8	1971	K060771
39 3/8	999	K060388	57 7/8	1471	K060573	77 7/8	1977	K060772
39 3/4	1008	K060390	58	1473	K060575	78	1982	K060775
39 7/8	1012	K060393	58 3/8	1483	K060578	78 1/4	1988	K060776
40	1016	K060394	58 3/4	1492	K060583	78 5/8	1996	K060780
40 1/4	1022	+ K060396A	59 1/4	1504	K060586	79	2007	K060785
40 3/4	1034	K060400	59 3/8	1508	K060588	79 1/8	2010	K060787
41	1042	K060405	59 5/8	1515	K060591	79 1/2	2018	K060790
41 1/4	1050	K060406	60	1523	K060594	79 3/4	2026	K060792
41 3/8	1051	K060407	60 3/8	1534	K060598	80 1/8	2034	K060795
41 1/2	1054	K060408	60 3/4	1542	K060602	80 3/8	2040	K060798
41 1/2	1054	K060409	60 7/8	1547	K060604	80 3/8	2043	* DK060791
41 5/8	1058	K060410	61 1/8	1553	K060605	80 3/4	2051	K060802
42	1067	K060415	61 1/2	1563	K060609	81	2057	K060804
42 3/8	1076	K060418	61 3/4	1569	K060612	81 1/8	2061	K060806
42 1/2	1080	K060420	62 1/8	1577	K060615	81 5/8	2073	K060810
42 7/8	1089	K060423	62 5/8	1591	K060620	81 3/4	2076	K060812
43 1/8	1095	K060425	62 7/8	1598	K060623	82	2083	* DK060809
			63 1/8	1603	K060625	82 1/8	2085	K060815
			63 3/8	1610	K060628	82 1/2	2093	K060819

\* Dual Side Belt + Aramid Cord

Size Lists



MICRO-V® BELTS – LISTED BY SIZE

Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>13/16" (20 mm) Top Width - Cont.</b>			<b>13/16" (20 mm) Top Width - Cont.</b>			<b>15/16" (24 mm) Top Width</b>		
82 1/2	2096	K060820	96 5/8	2453	K060960	32 1/2	826	K070319
82 3/4	2102	K060822	96 7/8	2460	K060962	36 7/8	935	K070362
83	2108	K060824	97 1/8	2468	K060966	37 1/8	943	■ K070365EMD
83 1/8	2112	K060825	97 5/8	2479	K060970	37 3/4	957	K070370
83 1/4	2116	K060827	98 1/8	2492	K060975	38 5/8	981	K070381
83 3/8	2118	+ K060827A	98 5/8	2504	* DK060973	38 5/8	981	■ K070381EMD
83 3/8	2119	K060828	98 5/8	2505	K060980	39 3/4	1008	K070390
83 3/4	2127	K060832	99	2513	K060984	41 1/4	1048	K070407
84	2134	K060834	99 1/4	2520	K060986	41 1/4	1048	* K070407A
84	2134	+ K060834A	99 1/2	2526	K060988	42	1068	K070415
84 1/4	2140	K060837	99 5/8	2531	K060990	42	1068	■ K070415EMD
84 1/4	2140	+ K060837A	99 7/8	2537	K060994	43 1/8	1095	K070425
84 1/2	2146	K060840	100	2539	K060995	44 7/8	1140	K070443
84 1/2	2146	+ K060840A	100 1/4	2546	K060997	45 3/8	1153	K070448
84 5/8	2149	K060841	100 5/8	2555	K061000	49 5/8	1261	■ K070491EMD
84 3/4	2153	K060842	100 3/4	2559	K061002	50 5/8	1286	K070500
85 1/4	2165	K060845	101 1/8	2568	K061005	51 1/8	1300	K070505
85 1/2	2171	K060849	101 5/8	2581	K061010	51 3/8	1305	K070508
85 5/8	2175	K060850	102 1/8	2593	K061015	51 3/8	1305	■ K070508EMD
85 5/8	2175	+ K060851A	102 1/4	2596	K061016	54 1/2	1385	K070539
85 7/8	2182	K060854	102 5/8	2605	K061020	54 3/4	1391	K070542
85 7/8	2182	+ K060854A	103	2615	K061025	54 7/8	1394	* DK070536
86 3/8	2193	K060858	103 5/8	2633	K061031	55 7/8	1418	K070553
86 5/8	2201	K060860	103 7/8	2639	K061033	56 3/8	1432	* DK070551
86 5/8	2200	+ K060861A	104 1/4	2649	K061037	56 7/8	1445	K070563
86 7/8	2206	K060863	105	2666	K061045	57	1448	K070565
86 7/8	2208	K060864	105 1/2	2680	K061049	57 1/4	1454	K070566
87 1/8	2213	* DK060859	106	2692	K061054	58 3/8	1483	K070578
87 1/4	2216	K060866	106 3/8	2701	K061058	61 5/8	1564	K070610
87 1/4	2216	+ K060867A	106 3/4	2711	K061062	62 1/8	1578	K070615
87 3/8	2219	K060868	107 1/8	2722	K061066	62 3/4	1594	K070622
87 5/8	2225	K060870	107 7/8	2741	K061073	63 3/8	1609	K070628
87 7/8	2232	* DK060867	108 1/8	2746	K061075	63 5/8	1616	K070630
87 7/8	2232	+ K060873A	108 1/4	2750	K061077	64 5/8	1642	K070640
87 7/8	2233	K060874	108 3/4	2761	K061080	65	1651	K070644
88	2235	+ K060874A	109 3/4	2788	K061093	66 1/2	1688	K070649
88 1/8	2238	K060875	109 3/8	2780	K061098	65 7/8	1675	K070653
88 1/8	2239	K060876	110 1/2	2807	K061099	66	1678	K070655
88 3/8	2245	K060878	110 3/4	2814	K061102	66 3/4	1695	K070663
88 1/2	2248	+ K060880A	111 1/8	2824	K061105	67 1/4	1708	K070667
88 7/8	2257	K060882	111 5/8	2835	K061110	67 1/2	1716	K070669
89	2261	K060883	111 7/8	2841	K061115	67 3/4	1722	K070673
89 1/8	2263	K060885	112 1/2	2859	K061120	68 1/4	1734	K070677
89	2261	+ K060885A	112 7/8	2869	K061123	68 5/8	1743	K070680
89 1/8	2265	K060886	113 5/8	2886	K061130	68 7/8	1750	K070683
89 1/2	2273	K060888	114 1/2	2910	K061140	69 1/8	1756	K070685
89 3/4	2278	K060891	114 5/8	2911	K061141	69 1/2	1767	K070690
89 7/8	2283	K060893	115 1/4	2927	K061145	70	1779	K070694
89 7/8	2283	+ K060893A	118 1/4	3005	K061177	70 3/4	1796	K070701
90 1/8	2289	K060895	119 1/4	3030	K061187	71 1/8	1807	K070705
90 1/8	2289	+ K060895A	120 1/8	3051	K061195	71 1/2	1816	K070709
90 5/8	2302	* DK060901	120 7/8	3069	K061203	72	1829	K070714
90 5/8	2301	K060900	123 5/8	3137	K061230	72 3/4	1847	K070721
90 7/8	2308	K060905	125 1/4	3183	K061247	73 5/8	1870	K070730
90 7/8	2308	+ K060905A	125 5/8	3192	K061251	73 3/4	1874	K070733
91 1/4	2318	K060908	127	3226	K061265	74 1/8	1883	K070735
91 1/4	2318	+ K060908A	128 5/8	3267	K061280	75 5/8	1920	K070750
91 5/8	2329	K060910	130 3/8	3312	K061298	76	1930	7PK1930
91 3/4	2330	+ K060911A	136 1/2	3467	K061360	76 1/8	1933	K070755
92	2337	K060913	137 1/2	3492	K061369	76 7/8	1951	K070763
92 1/8	2340	K060915	137 7/8	3502	K061373	78	1982	K070776
92 1/8	2340	+ K060916A	138 5/8	3519	K061380	79 1/8	2011	K070786
92 3/8	2346	K060919	138 5/8	3521	+ K061380A	80	2033	K070795
92 3/8	2346	+ K060919A	139 9/16	3559	+ K061395A	80 3/4	2051	K070801
92 7/8	2360	K060923	142 1/2	3621	K061420	81 5/8	2073	K070810
93 1/8	2364	K060926	149 1/2	3799	K061490	81 1/2	2070	+ K070810A
93 1/4	2369	K060928	<b>3/16" (21 mm) Top Width</b>			82 3/4	2102	K070822
93 5/8	2377	K060930	46 27/32	1190	6PK1190	82 7/8	2105	* DK070817
94	2387	K060935	65 1/2	1660	6PK1660	83 1/8	2112	K070825
94 1/2	2400	K060938	73	1856	6PK1856	83 5/8	2124	K070830
94 3/4	2407	K060942	74 7/16	1877	6PK1880	84	2133	K070834
95 1/8	2415	K060945	73 7/8	1882	6PK1882	84	2134	K070835
95 1/4	2419	K060947	74 13/32	1890	6PK1890	85 1/8	2164	7PK2164
95 5/8	2428	K060950	82 3/8	2090	6PK2090	85 1/4	2164	K070846
95 3/4	2432	* DK060956				85 3/4	2178	K070852
95 3/4	2432	K060952				86 1/8	2187	K070855
96 1/8	2440	K060956				87 9/32	2217	7PK2217
						87 7/8	2232	K070873
						88 1/2	2249	K070880

■ Electro-Mechanical Drive Belt \* Dual Side Belt + Aramid Cord

MICRO-V® BELTS – LISTED BY SIZE



Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>15/16" (24 mm) Top Width - Cont.</b>			<b>1 3/32" (28 mm) Top Width - Cont.</b>			<b>1 3/32" (28 mm) Top Width - Cont.</b>		
88 3/4	2255	K070882	56 5/8	1438	* DK080555	84 3/4	2154	K080842
89 1/8	2263	K070885	56 5/8	1439	K080560	85 3/4	2178	K080852
89 1/8	2265	K070886	57	1448	K080565	86 1/8	2187	K080855
90 1/8	2289	K070896	57 1/8	1452	K080566	86 3/8	2195	K080859
90 5/8	2301	K070901	57 3/8	1457	* DK080568	87 1/8	2212	K080865
90 7/8	2308	K070903	57 1/2	1462	* DK080562	87 3/4	2230	K080872
91 1/8	2314	K070905	57 1/2	1462	K080570	88 1/8	2240	K080876
92 1/4	2343	K070916	57 7/8	1470	* DK080566	88 3/8	2245	K080878
92 3/4	2357	K070922	58 1/8	1475	K080575	89 7/8	2282	K080893
93	2362	K070924	58 5/8	1490	K080580	90 3/8	2295	K080897
93 5/8	2378	K070931	59	1499	K080585	90 7/8	2308	K080903
95 3/4	2431	K070951	59 1/2	1512	K080590	91 1/4	2318	K080907
96 3/4	2457	K070961	60	1523	K080594	91 5/8	2326	K080910
97 3/4	2481	K070971	60 5/8	1538	K080600	91 7/8	2334	K080913
97 3/4	2484	K070975	61 1/8	1553	K080605	92 1/8	2340	K080915
98 1/8	2492	K070976	61 3/4	1569	K080610	92 3/4	2355	K080922
101 1/8	2568	K071005	62 1/8	1577	K080615	93 1/8	2367	K080926
101 3/8	2576	K071009	62 1/4	1581	K080616	93 7/8	2384	K080934
101 7/8	2586	K071013	62 3/8	1584	K080618	94 1/2	2400	K080939
103 5/8	2633	K071031	62 5/8	1591	K080620	95	2412	K080944
104 1/4	2649	K071037	62 7/8	1598	K080623	95 3/8	2424	K080948
104 5/8	2656	K071040	63 1/8	1603	K080626	95 3/4	2432	K080952
105 1/8	2671	K071045	63 1/2	1613	K080627	96 1/4	2444	K080956
106 1/4	2699	K071056	63 5/8	1616	K080630	97 1/2	2475	K080968
107 1/8	2720	K071065	64 1/4	1633	K080635	98 1/4	2496	K080976
113 5/8	2886	K071130	65	1651	K080644	98 5/8	2505	K080981
114	2897	K071134	65 1/4	1657	K080645	99 1/8	2519	K080986
114 1/8	2899	* DK071135	65 1/2	1665	K080649	99 5/8	2531	K080991
114 5/8	2912	K071141	65 7/8	1674	K080653	100 5/8	2555	K081000
115 5/8	2936	K071150	66 1/4	1683	K080655	101 1/8	2568	K081005
116 1/4	2953	K071157	66 1/2	1691	K080660	102 5/8	2605	K081020
119 7/8	3046	K071194	66 3/4	1695	+ K080661A	102 7/8	2613	K081023
121 7/8	3096	K071213	66 3/4	1695	K080662	104	2642	K081035
125 3/8	3183	K071247	67 1/8	1705	K080665	104 1/32	2661	K081040
<b>1 3/32" (28 mm) Top Width</b>			67 1/2	1716	K080670	105 3/4	2686	K081051
30 3/4	781	K080300	67 3/4	1722	K080672	106 1/2	2705	K081059
33 3/4	856	K080330	68	1728	K080675	106 7/8	2715	K081062
34	864	K080334	68 1/4	1734	K080677	108	2745	K081074
36 3/4	932	K080360	68 5/8	1742	K080680	108 1/2	2756	K081079
37 1/8	943	K080365	69 1/8	1756	K080685	109 3/8	2778	K081088
37 3/4	957	K080370	69 5/8	1767	K080690	109 3/4	2788	K081092
38 1/8	968	K080375	70	1777	K080694	110 3/4	2814	K081102
38 3/4	983	K080382	70 1/2	1789	K080700	113	2869	K081124
39	990	K080384	70 3/4	1798	K080702	113 3/4	2889	K081131
39 3/4	1008	K080390	71 1/4	1811	K080708	115 1/8	2924	K081145
39 7/8	1014	K080392	71 1/2	1816	K080710	116 1/4	2953	K081153
40 3/4	1034	K080400	71 3/4	1822	K080712	118 1/4	3005	K081177
41 3/8	1051	K080408	72 1/8	1831	K080716	118 5/8	3013	K081181
42 1/8	1069	K080415	72 5/8	1845	K080720	119 1/2	3035	K081189
43	1091	K080424	73 1/4	1859	K080726	120 1/8	3050	K081196
43 1/2	1103	K080427	73 1/2	1867	K080730	121 3/8	3082	K081207
44 1/8	1122	K080435	73 3/4	1874	K080733	121 7/8	3096	K081213
45 5/8	1160	K080450	74	1880	K080734	122 3/4	3117	K081223
46	1170	K080455	74 3/8	1889	K080738	124 7/8	3172	K081243
46 3/8	1179	K080458	74 5/8	1896	K080740	125 7/8	3198	K081253
47	1195	K080465	75 1/8	1907	K080745	126	3200	* DK081254
47 3/4	1211	K080471	75 5/8	1921	K080751	127	3227	K081264
49 1/8	1249	K080485	76	1931	K080755	127 1/8	3228	K081265
49 5/8	1260	K080491	76 1/2	1942	K080760	130 3/8	3312	K081298
50 1/8	1274	K080496	77	1957	K080765	133 1/8	3381	K081325
51	1297	K080505	77 3/4	1976	K080774	133 3/4	3396	K081331
51 1/4	1302	K080507	78 1/8	1985	K080776	135 3/8	3439	K081348
51 1/2	1309	K080510	78 5/8	1996	K080780	135 3/4	3448	K081352
52	1320	K080514	79	2007	K080785	136 1/2	3468	K081359
52 1/8	1324	K080515	79 1/2	2019	K080790	136 3/4	3474	K081362
52 3/4	1340	K080522	79 5/8	2022	K080791	138 1/4	3513	K081377
53 1/8	1351	K080525	80 1/8	2037	K080797	140 3/4	3575	* DK081396
53 3/8	1356	* DK080522	80 7/8	2054	K080803	140 7/8	3579	* DK081403
53 1/2	1359	K080530	81 1/8	2061	K080806	149 1/2	3799	K081490
54	1370	* DK080534	81 3/8	2067	K080808	<b>1 7/32" (31 mm) Top Width</b>		
54 1/4	1379	K080537	81 5/8	2073	K080810	50 1/2	1282	K090500
55 1/8	1399	K080545	82 1/8	2086	K080816	61 1/2	1562	K090609
55 1/4	1403	K080547	82 3/8	2091	K080817			
55 3/4	1415	K080550	82 3/4	2100	K080820			
56 1/4	1429	K080558	83 1/8	2112	K080825			
			83 3/4	2127	K080830			
			84 3/8	2144	K080839			

\* Dual Side Belt + Aramid Cord



Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>1 3/8" (35 mm) Top Width</b>			<b>1 3/8" (35 mm) Top Width - Cont.</b>			<b>1 21/32" (42 mm) Top Width - Cont.</b>		
38 3/4	983	K100381	81 5/8	2073	K100810	86 3/8	2194	K120858
44 1/4	1124	K100437	82 1/8	2086	K100816	86 7/8	2208	K120864
45 1/8	1148	K100445	84 5/8	2149	K100840	87 3/4	2230	K120872
46 1/8	1173	K100456	85 7/8	2182	K100852	88 1/8	2239	K120876
47	1195	K100465	87	2210	K100864	88 3/8	2245	K120878
47 1/4	1200	+ K100467A	89	2261	K100884	89 5/8	2278	K120891
48 7/8	1241	K100485	89 1/8	2264	K100886	90 5/8	2301	K120901
50 1/8	1274	K100495	89 3/4	2278	K100891	90 7/8	2308	K120903
50 3/4	1288	K100502	92 5/8	2354	K100921	91 1/8	2315	K120905
51 1/2	1309	K100510	94 5/8	2404	K100938	91 3/4	2329	K120911
54	1373	K100535	96	2438	K100955	92 1/8	2340	K120915
54 1/2	1385	K100540	98 1/8	2492	K100976	92 1/2	2350	K120919
56	1423	K100554	100 3/8	2550	K100998	93 1/8	2364	K120924
56 7/8	1444	K100563	101 1/8	2569	K101005	93 3/4	2381	K120931
57 1/2	1462	K100570	108 3/8	2753	K101078	97	2463	K120964
57 7/8	1469	K100572	84 3/4	2153	K110841	98 1/8	2492	K120979
58 1/8	1475	K100575	<b>1 21/32" (42 mm) Top Width</b>			104 1/2	2654	K121039
58 1/2	1487	K100579	28 3/4	730	K120281	113	2870	K121124
59 1/4	1505	K100586	36 5/8	929	K120360	35	890	K140345
60	1523	K100594	39 3/4	1008	K120390	35 7/8	910	K140352
60 7/8	1547	K100601	40 3/4	1034	K120400	37 1/2	954	K140370
61 1/4	1557	K100607	41 1/2	1054	K120410	43 1/2	1106	K140429
61 5/8	1564	K100610	46 1/4	1175	K120457	43 7/8	1116	K140433
61 7/8	1572	K100613	46 7/8	1191	K120463	45 5/8	1160	K140451
62 3/8	1585	K100618	48 1/4	1226	K120476	50 1/8	1274	K140496
63 5/8	1616	K100630	48 7/8	1241	K120483	52 1/8	1325	K140516
84 3/4	2153	K100635	53 1/8	1351	K120525	53 1/8	1350	K140524
64 1/4	1633	K100637	56 1/2	1436	K120559	56	1422	K140555
64 5/8	1642	K100640	60	1523	K120594	58 5/8	1490	K140580
66	1678	K100655	61 1/8	1553	K120606	60	1523	K140594
66 3/8	1687	K100658	61 3/4	1569	K120610	60 3/8	1534	K140597
67 1/8	1704	K100665	67 3/16	1707	K120664	60 7/8	1546	K140603
67 1/2	1716	K100670	67 5/8	1718	K120671	62 3/8	1585	K140618
68	1728	K100675	70 3/4	1798	K120702	63 3/8	1609	K140627
68 1/4	1734	K100677	72 5/8	1845	K120720	66 3/4	1696	K140662
68 3/8	1737	* DK100672	74	1880	K120734	68 3/4	1746	K140682
70	1778	K100694	74 3/8	1889	K120738	70 1/2	1789	K140700
71 1/2	1816	K100710	79	2007	K120784	101 5/8	2582	+ K141009A
72 3/8	1840	K100719	82	2083	K120815	<b>2 1/16" (53 mm) Top Width</b>		
73 5/8	1871	K100731	83 1/8	2111	K120825	76 3/8	1942	K150759
74 1/2	1893	K100739	84 3/4	2154	K120842			
75	1905	* DK100744	85 3/4	2178	K120852			
75 3/8	1915	* DK100743						
75 1/2	1918	K100749						
77 3/4	1976	K100771						
79 1/2	2019	K100789						

\* Dual Side Belt + Aramid Cord





## Showing Micro-V® Belts With Corresponding Top Widths, Nominal Lengths and Number of Ribs

Industrial Micro-V® Belts are identified by a three-part symbol consisting of:

1. Standard Length Designation
2. Cross Section
3. Number of Ribs

For example, the belt designation **780L12** represents:

- (1.) 78.0" in Length
- (2.) L Cross Section
- (3.) 12 Ribs Wide

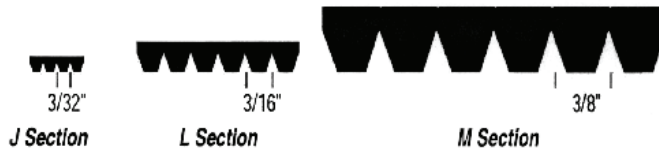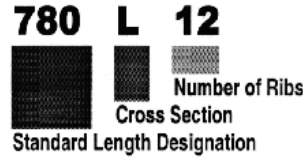

NOTE: Rib combinations noted are RMA standard configurations. Belts available in most multiples.

Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)
<b>J Section 2 Ribs</b>			<b>J Section - Cont. 4 Ribs - Cont.</b>			<b>J Section - Cont. 6 Ribs - Cont.</b>		
180J2.....	18	457	190J4.....	19	483	190J6.....	19	483
190J2.....	19	483	200J4.....	20	508	200J6.....	20	508
200J2.....	20	508	220J4.....	22	559	220J6.....	22	559
220J2.....	22	559	230J4.....	23	584	230J6.....	23	584
230J2.....	23	584	240J4.....	24	610	240J6.....	24	610
240J2.....	24	610	260J4.....	26	660	260J6.....	26	660
260J2.....	26	660	280J4.....	28	711	280J6.....	28	711
280J2.....	28	711	290J4.....	29	737	290J6.....	29	737
290J2.....	29	737	300J4.....	30	762	300J6.....	30	762
300J2.....	30	762	320J4.....	32	813	320J6.....	32	813
320J2.....	32	813	330J4.....	33	838	330J6.....	33	838
330J2.....	33	838	340J4.....	34	864	340J6.....	34	864
340J2.....	34	864	360J4.....	36	914	360J6.....	36	914
360J2.....	36	914	380J4.....	38	965	380J6.....	38	965
380J2.....	38	965	400J4.....	40	1016	400J6.....	40	1016
400J2.....	40	1016	410J4.....	41	1041	410J6.....	41	1041
410J2.....	41	1041	420J4.....	42	1067	420J6.....	42	1067
420J2.....	42	1067	430J4.....	43	1092	430J6.....	43	1092
430J2.....	43	1092	440J4.....	44	1118	440J6.....	44	1118
440J2.....	44	1118	460J4.....	46	1168	460J6.....	46	1168
460J2.....	46	1168	480J4.....	48	1219	480J6.....	48	1219
480J2.....	48	1219	490J4.....	49	1245	490J6.....	49	1245
490J2.....	49	1245	500J4.....	50	1270	500J6.....	50	1270
500J2.....	50	1270	520J4.....	52	1321	520J6.....	52	1321
520J2.....	52	1321	550J4.....	55	1397	550J6.....	55	1397
550J2.....	55	1397	580J4.....	58	1473	580J6.....	58	1473
580J2.....	58	1473	610J4.....	61	1549	610J6.....	61	1549
610J2.....	61	1549	650J4.....	65	1651	650J6.....	65	1651
650J2.....	65	1651	730J4.....	73	1854	730J6.....	73	1854
730J2.....	73	1854	870J4.....	87	2210	870J6.....	87	2210
870J2.....	87	2210	920J4.....	92	2337	920J6.....	92	2337
920J2.....	92	2337	980J4.....	98	2489	980J6.....	98	2489
980J2.....	98	2489						
<b>4 Ribs</b>			<b>6 Ribs</b>			<b>8 Ribs</b>		
180J4.....	18	457	120J6.....	12	305	150J8.....	15	381
			180J6.....	18	457	180J8.....	18	457







Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)
<b>L Section - Cont.</b>			<b>L Section - Cont.</b>			<b>L Section - Cont.</b>		
<b>8 Ribs</b>			<b>12 Ribs - Cont.</b>			<b>18 Ribs - Cont.</b>		
500L8	50	1270	1065L12	106.5	2705	695L18	69.5	1765
540L8	54	1372	1120L12	112	2845	725L18	72.5	1842
560L8	56	1422	1150L12	115	2921	765L18	76.5	1943
615L8	61.5	1562	1215L12	121.5	3086	780L18	78	1981
635L8	63.5	1613	1230L12	123	3124	795L18	79.5	2019
655L8	65.5	1664	1295L12	129.5	3289	815L18	81.5	2070
675L8	67.5	1715	1310L12	131	3327	840L18	84	2134
695L8	69.5	1765	1455L12	145.5	3696	865L18	86.5	2197
725L8	72.5	1842				915L18	91.5	2324
765L8	76.5	1943	<b>14 Ribs</b>			975L18	97.5	2477
780L8	78	1981	500L14	50	1270	990L18	99	2515
795L8	79.5	2019	540L14	54	1372	1120L18	112	2845
815L8	81.5	2070	560L14	56	1422	1150L18	115	2921
840L8	84	2134	615L14	61.5	1562	1215L18	121.5	3086
865L8	86.5	2197	635L14	63.5	1613	1230L18	123	3124
915L8	91.5	2324	655L14	65.5	1664	1295L18	129.5	3289
975L8	97.5	2477	675L14	67.5	1715	1310L18	131	3327
990L8	99	2515	695L14	69.5	1765	1455L18	145.5	3696
1065L8	106.5	2705	725L14	72.5	1842			
1120L8	112	2845	765L14	76.5	1943	<b>20 Ribs</b>		
1150L8	115	2921	780L14	78	1981	500L20	50	1270
1215L8	121.5	3086	795L14	79.5	2019	540L20	54	1372
1230L8	123	3124	815L14	81.5	2070	560L20	56	1422
1295L8	129.5	3289	840L14	84	2134	615L20	61.5	1562
1310L8	131	3327	865L14	86.5	2197	635L20	63.5	1613
1455L8	145.5	3696	915L14	91.5	2324	655L20	65.5	1664
			975L14	97.5	2477	675L20	67.5	1715
			990L14	99	2515	695L20	69.5	1765
			1065L14	106.5	2705	725L20	72.5	1842
			1120L14	112	2845	765L20	76.5	1943
			1150L14	115	2921	780L20	78	1981
			1215L14	121.5	3086	795L20	79.5	2019
			1230L14	123	3124	815L20	81.5	2070
			1295L14	129.5	3289	840L20	84	2134
			1310L14	131	3327	865L20	86.5	2197
			1455L14	145.5	3696	915L20	91.5	2324
						975L20	97.5	2477
			<b>16 Ribs</b>			990L20	99	2515
			500L16	50	1270	1120L20	112	2845
			540L16	54	1372	1150L20	115	2921
			560L16	56	1422	1215L20	121.5	3086
			615L16	61.5	1562	1230L20	123	3124
			635L16	63.5	1613	1295L20	129.5	3289
			655L16	65.5	1664	1310L20	131	3327
			675L16	67.5	1715	1455L20	145.5	3696
			695L16	69.5	1765			
			725L16	72.5	1842	<b>M Section</b>		
			765L16	76.5	1943	<b>4 Ribs</b>		
			780L16	78	1981	1115M4	111.5	2832
			795L16	79.5	2019	1150M4	115	2921
			815L16	81.5	2070	1310M4	131	3327
			840L16	84	2134	1390M4	139	3531
			865L16	86.5	2197	2130M4	213	5410
			915L16	91.5	2324	2410M4	241	6121
			975L16	97.5	2477	2710M4	271	6883
			990L16	99	2515			
			1065L16	106.5	2705	<b>6 Ribs</b>		
			1120L16	112	2845	900M6	90	2286
			1150L16	115	2921	940M6	94	2388
			1215L16	121.5	3086	990M6	99	2515
			1230L16	123	3124	1060M6	106	2692
			1295L16	129.5	3289	1115M6	111.5	2832
			1310L16	131	3327	1150M6	115	2921
			1455L16	145.5	3696	1185M6	118.5	3010
						1230M6	123	3124
			<b>18 Ribs</b>			1310M6	131	3327
			500L18	50	1270	1390M6	139	3531
			540L18	54	1372	1470M6	147	3734
			560L18	56	1422	1610M6	161	4089
			615L18	61.5	1562	1650M6	165	4191
			635L18	63.5	1613	1760M6	176	4470
			655L18	65.5	1664	1830M6	183	4648
			675L18	67.5	1715			

Size Lists



# INDUSTRIAL MICRO-V® BELTS – LISTED BY NUMBER

Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)
<b>M Section - Cont.</b>			<b>M Section - Cont.</b>			<b>M Section - Cont.</b>		
<b>6 Ribs - Cont.</b>			<b>12 Ribs - Cont.</b>			<b>16 Ribs - Cont.</b>		
1980M6.....	198	5029	990M12.....	99	2515	1650M16.....	165	4191
2130M6.....	213	5410	1060M12.....	106	2692	1760M16.....	176	4470
2410M6.....	241	6121	1115M12.....	111.5	2832	1830M16.....	183	4648
2560M6.....	256	6502	1150M12.....	115	2921	1980M16.....	198	5029
2710M6.....	271	6883	1185M12.....	118.5	3010	2130M16.....	213	5410
3010M6.....	301	7645	1230M12.....	123	3124	2410M16.....	241	6121
3310M6.....	331	8407	1310M12.....	131	3327	2560M16.....	256	6502
3610M6.....	361	9169	1390M12.....	139	3531	2710M16.....	271	6883
<b>8 Ribs</b>			<b>14 Ribs</b>			<b>18 Ribs</b>		
900M8.....	90	2286	900M14.....	90	2286	900M18.....	90	2286
940M8.....	94	2388	940M14.....	94	2388	940M18.....	94	2388
990M8.....	99	2515	990M14.....	99	2515	990M18.....	99	2515
1060M8.....	106	2692	1060M14.....	106	2692	1060M18.....	106	2692
1115M8.....	111.5	2832	1115M14.....	111.5	2832	1115M18.....	111.5	2832
1150M8.....	115	2921	1150M14.....	115	2921	1150M18.....	115	2921
1185M8.....	118.5	3010	1185M14.....	118.5	3010	1185M18.....	118.5	3010
1230M8.....	123	3124	1230M14.....	123	3124	1230M18.....	123	3124
1310M8.....	131	3327	1310M14.....	131	3327	1310M18.....	131	3327
1390M8.....	139	3531	1390M14.....	139	3531	1390M18.....	139	3531
1470M8.....	147	3734	1470M14.....	147	3734	1470M18.....	147	3734
1610M8.....	161	4089	1610M14.....	161	4089	1610M18.....	161	4089
1650M8.....	165	4191	1650M14.....	165	4191	1650M18.....	165	4191
1760M8.....	176	4470	1760M14.....	176	4470	1760M18.....	176	4470
1830M8.....	183	4648	1830M14.....	183	4648	1830M18.....	183	4648
1980M8.....	198	5029	1980M14.....	198	5029	1980M18.....	198	5029
2130M8.....	213	5410	2130M14.....	213	5410	2130M18.....	213	5410
2410M8.....	241	6121	2410M14.....	241	6121	2410M18.....	241	6121
2560M8.....	256	6502	2560M14.....	256	6502	2560M18.....	256	6502
2710M8.....	271	6883	2710M14.....	271	6883	2710M18.....	271	6883
3010M8.....	301	7645	3010M14.....	301	7645	3010M18.....	301	7645
3310M8.....	331	8407	3310M14.....	331	8407	3310M18.....	331	8407
3610M8.....	361	9169	3610M14.....	361	9169	3610M18.....	361	9169
<b>10 Ribs</b>			<b>16 Ribs</b>			<b>20 Ribs</b>		
900M10.....	90	2286	900M16.....	90	2286	900M20.....	90	2286
940M10.....	94	2388	940M16.....	94	2388	940M20.....	94	2388
990M10.....	99	2515	990M16.....	99	2515	990M20.....	99	2515
1060M10.....	106	2692	1060M16.....	106	2692	1060M20.....	106	2692
1115M10.....	111.5	2832	1115M16.....	111.5	2832	1115M20.....	111.5	2832
1150M10.....	115	2921	1150M16.....	115	2921	1150M20.....	115	2921
1185M10.....	118.5	3010	1185M16.....	118.5	3010	1185M20.....	118.5	3010
1230M10.....	123	3124	1230M16.....	123	3124	1230M20.....	123	3124
1310M10.....	131	3327	1310M16.....	131	3327	1310M20.....	131	3327
1390M10.....	139	3531	1390M16.....	139	3531	1390M20.....	139	3531
1470M10.....	147	3734	1470M16.....	147	3734	1470M20.....	147	3734
1610M10.....	161	4089	1610M16.....	161	4089	1610M20.....	161	4089
1650M10.....	165	4191				1650M20.....	165	4191
1760M10.....	176	4470				1760M20.....	176	4470
1830M10.....	183	4648				1830M20.....	183	4648
1980M10.....	198	5029				1980M20.....	198	5029
2130M10.....	213	5410				2130M20.....	213	5410
2410M10.....	241	6121				2410M20.....	241	6121
2560M10.....	256	6502				2560M20.....	256	6502
2710M10.....	271	6883				2710M20.....	271	6883
3010M10.....	301	7645				3010M20.....	301	7645
3310M10.....	331	8407				3310M20.....	331	8407
3610M10.....	361	9169				3610M20.....	361	9169
<b>12 Ribs</b>								
900M12.....	90	2286						
940M12.....	94	2388						



## Showing Belt Numbers with Corresponding Nominal Outside Lengths and Top Widths

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
9290HD	29 3/8	746	1/2	13	9490HD	49 3/8	1254	1/2	13
9305HD	30 7/8	784	1/2	13	9495HD	49 29/32	1268	1/2	13
9309HD	31 5/16	795	1/2	13	9500HD	50 7/16	1281	1/2	13
9313HD	31 7/8	810	1/2	13	9505HD	50 7/8	1292	1/2	13
9319HD	32 5/8	830	1/2	13	9510HD	51 3/8	1305	1/2	13
9325HD	32 7/8	835	1/2	13	9520HD	52 7/16	1332	1/2	13
9330HD	33 3/8	848	1/2	13	9525HD	52 7/8	1343	1/2	13
9335HD	33 29/32	862	1/2	13	9530HD	53 7/16	1357	1/2	13
9341HD	34 3/8	873	1/2	13	9540HD	54 3/8	1382	1/2	13
9345HD	34 7/8	886	1/2	13	9545HD	54 27/32	1393	1/2	13
9350HD	35 15/32	901	1/2	13	9550HD	55 13/32	1408	1/2	13
9355HD	35 31/32	914	1/2	13	9555HD	55 27/32	1418	1/2	13
9360HD	36 3/8	924	1/2	13	9560HD	56 13/32	1433	1/2	13
9365HD	36 7/8	936	1/2	13	9565HD	56 27/32	1443	1/2	13
9370HD	37 3/8	950	1/2	13	9570HD	57 13/32	1458	1/2	13
9375HD	37 15/16	963	1/2	13	9580HD	58 3/8	1483	1/2	13
9380HD	38 3/8	975	1/2	13	9585HD	58 7/8	1496	1/2	13
9385HD	38 29/32	989	1/2	13	9590HD	59 13/32	1509	1/2	13
9390HD	39 3/8	1000	1/2	13	9600HD	60 13/32	1534	1/2	13
9395HD	39 29/32	1013	1/2	13	9605HD	60 31/32	1549	1/2	13
9400HD	40 3/8	1026	1/2	13	9610HD	61 7/16	1561	1/2	13
9403HD	40 5/8	1032	1/2	13	9620HD	62 3/8	1584	1/2	13
9405HD	40 27/32	1038	1/2	13	9625HD	62 7/8	1597	1/2	13
9412HD	41 3/8	1051	1/2	13	9630HD	63 13/32	1610	1/2	13
9415HD	41 29/32	1065	1/2	13	9635HD	63 29/32	1623	1/2	13
9420HD	42 11/32	1075	1/2	13	9640HD	64 3/8	1635	1/2	13
9425HD	42 27/32	1088	1/2	13	9650HD	65 3/8	1661	1/2	13
9430HD	43 7/16	1103	1/2	13	9660HD	66 3/8	1686	1/2	13
9435HD	43 7/8	1115	1/2	13	9670HD	67 3/8	1712	1/2	13
9440HD	44 3/8	1127	1/2	13	9680HD	68 3/8	1737	1/2	13
9447HD	44 27/32	1139	1/2	13	9690HD	69 3/8	1762	1/2	13
9451HD	45 7/16	1154	1/2	13	9700HD	70 3/8	1788	1/2	13
9455HD	45 27/32	1165	1/2	13	9710HD	71 3/8	1813	1/2	13
9463HD	46 3/8	1178	1/2	13	9720HD	72 3/8	1838	1/2	13
9465HD	46 27/32	1190	1/2	13	9730HD	73 11/32	1863	1/2	13
9470HD	47 3/8	1203	1/2	13	9740HD	74 7/8	1901	1/2	13
9476HD	47 15/16	1218	1/2	13	9745HD	74 7/8	1900	1/2	13
9480HD	48 15/32	1231	1/2	13	9755HD	75 15/16	1929	1/2	13
9485HD	48 27/32	1240	1/2	13					

All FleetRunner Heavy-Duty V-Belts are Notched



Showing Nominal Belt Top Widths and Outside Lengths  
with Our Corresponding Belt Numbers

Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>1/2" (13 mm) Top Width</b>			<b>1/2" (13 mm) Top Width - Cont.</b>			<b>1/2" (13 mm) Top Width - Cont.</b>		
29 3/8	746	9290HD	43 7/16	1103	9430HD	56 27/32	1443	9565HD
30 7/8	784	9305HD	43 7/8	1115	9435HD	57 13/32	1458	9570HD
31 5/16	795	9309HD	44 3/8	1127	9440HD	58 3/8	1483	9580HD
31 7/8	810	9313HD	44 27/32	1139	9447HD	58 7/8	1496	9585HD
32 5/8	830	9319HD	45 7/16	1154	9451HD	59 13/32	1509	9590HD
32 7/8	835	9325HD	45 27/32	1165	9455HD	60 13/32	1534	9600HD
33 3/8	848	9330HD	46 3/8	1178	9463HD	60 31/32	1549	9605HD
33 29/32	862	9335HD	46 27/32	1190	9465HD	61 7/16	1561	9610HD
34 3/8	873	9341HD	47 3/8	1203	9470HD	62 3/8	1584	9620HD
34 7/8	886	9345HD	47 15/16	1218	9476HD	62 7/8	1597	9625HD
35 15/32	901	9350HD	48 15/32	1231	9480HD	63 13/32	1610	9630HD
35 31/32	914	9355HD	48 27/32	1240	9485HD	63 29/32	1623	9635HD
36 3/8	924	9360HD	49 3/8	1254	9490HD	64 3/8	1635	9640HD
36 7/8	936	9365HD	49 29/32	1268	9495HD	65 3/8	1661	9650HD
37 3/8	950	9370HD	50 7/16	1281	9500HD	66 3/8	1686	9660HD
37 15/16	963	9375HD	50 7/8	1292	9505HD	67 3/8	1712	9670HD
38 3/8	975	9380HD	51 3/8	1305	9510HD	68 3/8	1737	9680HD
38 29/32	989	9385HD	52 7/16	1332	9520HD	69 3/8	1762	9690HD
39 3/8	1000	9390HD	52 7/8	1343	9525HD	70 3/8	1788	9700HD
39 29/32	1013	9395HD	53 7/16	1357	9530HD	71 3/8	1813	9710HD
40 3/8	1026	9400HD	54 3/8	1382	9540HD	72 3/8	1838	9720HD
40 5/8	1032	9403HD	54 27/32	1393	9545HD	73 11/32	1863	9730HD
40 27/32	1038	9405HD	55 13/32	1408	9550HD	74 7/8	1901	9740HD
41 3/8	1051	9412HD	55 27/32	1418	9555HD	74 7/8	1900	9745HD
41 29/32	1065	9415HD	56 13/32	1433	9560HD	75 15/16	1929	9755HD
42 11/32	1075	9420HD						
42 27/32	1088	9425HD						

All FleetRunner Heavy-Duty V-Belts are Notched






## Showing Belt Numbers with Corresponding Nominal Outside Lengths and Top Widths

IMPORTANT: Lengths shown (O.C. is Outside Circumference) are obtained by measuring around the outside of the belt. These lengths will not agree exactly with the size significant belt numbering system which is based on the effective length of the belt. Effective length ("engineered" length) cannot be measured in the field because special tools are required.

Automotive Top Widths are the standard sizes defined by the automotive belt industry (SAE J636). Due to manufacturing processes that create "Vertical Flats", the top width of XL and Truck/Bus series V-Belts will not agree with the printed top width dimensions. Top width on this page and on the belt sleeve refers to the pulley groove width and not the actual top width of these belts. A picture of a V-Belt with "Vertical Flats" is shown below. Actual top width of like belt sizes will also vary slightly depending on the manufacturer and belt style.



Competitive V-Belt

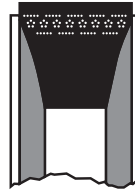

Our V-Belts with "Vertical Flats"

Belt Number	Section	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Section	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
7208.....	▼ HC41	21 1/4	540	13/32	10	7370.....	▼ HC41	37 5/8	954	13/32	10
7215.....	▼ HC41	22 1/8	561	13/32	10	7374.....	HC31	37 3/4	960	5/16	8
7228.....	HC31	23	585	5/16	8	7375.....	▼ HC41	38 1/8	967	13/32	10
7234.....	HC31	23 7/8	605	5/16	8	7379.....	HC31	38 1/4	970	5/16	8
7240.....	▼ HC41	24 5/8	624	13/32	10	7380.....	▼ HC41	38 5/8	980	13/32	10
7250.....	▼ HC41	25 5/8	650	13/32	10	7381.....	HC25	38 1/4	970	1/4	6
7255.....	▼ HC41	26 1/8	663	13/32	10	7384.....	HC31	38 3/4	985	5/16	8
7260.....	▼ HC41	26 5/8	675	13/32	10	7385.....	▼ HC41	39 1/8	993	13/32	10
7261.....	HC25	26 1/4	665	1/4	6	7388.....	HC25	39 1/4	995	1/4	6
7265.....	▼ HC41	27 1/8	688	13/32	10	7389.....	HC31	39 1/4	995	5/16	8
7270.....	▼ HC41	27 5/8	701	13/32	10	7390.....	▼ HC41	39 5/8	1005	13/32	10
7274.....	HC31	27 3/8	690	5/16	8	7395.....	▼ HC41	40 1/8	1018	13/32	10
7279.....	HC25	28 3/8	720	1/4	6	7400.....	▼ HC41	40 5/8	1031	13/32	10
7280.....	▼ HC41	28 5/8	726	13/32	10	7404.....	HC31	40 3/4	1035	5/16	8
7290.....	▼ HC41	29 5/8	751	13/32	10	7405.....	▼ HC41	41 1/8	1044	13/32	10
7292.....	▼ HC41	29 7/8	758	13/32	10	7409.....	HC25	41 1/4	1050	1/4	6
7295.....	▼ HC41	30 1/8	764	13/32	10	7410.....	▼ HC41	41 5/8	1056	13/32	10
7298.....	HC25	30 1/4	770	1/4	6	7417.....	▼ HC41	42 1/8	1069	13/32	10
7300.....	▼ HC41	30 5/8	777	13/32	10	7419.....	HC31	42 1/4	1075	5/16	8
7304.....	HC31	30 3/4	780	5/16	8	7420.....	▼ HC41	42 5/8	1082	13/32	10
7305.....	▼ HC41	31 1/8	792	13/32	10	7425.....	▼ HC41	43 1/8	1095	13/32	10
7309.....	HC25	31 1/4	795	1/4	6	7430.....	▼ HC41	43 5/8	1107	13/32	10
7312.....	▼ HC41	31 5/8	802	13/32	10	7435.....	▼ HC41	44 1/8	1120	13/32	10
7315.....	▼ HC41	32 1/8	815	13/32	10	7440.....	▼ HC41	44 5/8	1132	13/32	10
7318.....	HC25	32 1/4	820	1/4	6	7444.....	HC31	44 3/4	1135	5/16	8
7320.....	▼ HC41	32 5/8	828	13/32	10	7445.....	▼ HC41	45 1/8	1145	13/32	10
7324.....	HC31	32 5/8	830	5/16	8	7447M...	⊗ HC38 MODIFIED	45 1/4	1149	13/32	10
7325.....	▼ HC41	33 1/8	840	13/32	10	7448.....	▼ HC41	45 3/8	1151	13/32	10
7328.....	▼ HC41	33 3/8	847	13/32	10	7449.....	HC31	45 1/4	1150	5/16	8
7329.....	HC25	33 1/4	845	1/4	6	7450.....	THC41	45 5/8	1158	13/32	10
7330.....	▼ HC41	33 5/8	853	13/32	10	7453.....	THC41	45 7/8	1164	13/32	10
7333.....	HC25	34 1/4	870	1/4	6	7455.....	THC41	46 1/8	1171	13/32	10
7334.....	HC31	33 3/4	855	5/16	8	7459.....	HC31	46 1/4	1175	5/16	8
7335.....	▼ HC41	34 1/8	866	13/32	10	7460.....	THC41	46 5/8	1183	13/32	10
7340.....	▼ HC41	34 5/8	878	13/32	10	7465.....	THC41	47 1/8	1196	13/32	10
7343.....	HC31	34 1/4	870	5/16	8	7470.....	THC41	47 5/8	1209	13/32	10
7345.....	▼ HC41	35 1/8	891	13/32	10	7473.....	THC41	47 7/8	1215	13/32	10
7348.....	HC25	35 1/4	895	1/4	6	7475.....	▼ HC41	48 1/8	1221	13/32	10
7350.....	▼ HC41	35 5/8	904	13/32	10	7480.....	▼ HC41	48 5/8	1234	13/32	10
7355.....	▼ HC41	36 1/8	919	13/32	10	7483.....	▼ HC41	48 7/8	1242	13/32	10
7359.....	HC25	36 1/4	920	1/4	6	7485.....	▼ HC41	49 1/8	1247	13/32	10
7360.....	▼ HC41	36 5/8	929	13/32	10	7490.....	▼ HC41	49 5/8	1260	13/32	10
7362.....	HC31	36 3/8	925	5/16	8	7495.....	▼ HC41	50 1/8	1272	13/32	10
7363.....	HC25	36 3/4	935	1/4	6	7496.....	HC31	49 5/8	1260	5/16	8
7365.....	▼ HC41	37 1/8	942	13/32	10	7500.....	▼ HC41	50 5/8	1285	13/32	10
7369.....	HC31	37 1/4	945	5/16	8	7508.....	▼ HC41	51 1/8	1297	13/32	10

▼ Notched Belt    ⊗ Set of Two Belts



# XL® V-BELTS – LISTED BY NUMBER

Belt Number	Section	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Section	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
7512	▼ HC41	51 5/8	1310	13/32	10	9403	▼ HC50	40 5/8	1032	15/32	12
7516	▼ HC41	52 1/8	1323	13/32	10	9405	▼ HC50	40 7/8	1038	15/32	12
7520	▼ HC41	52 5/8	1336	13/32	10	9412	▼ HC50	41 3/8	1051	15/32	12
7525	▼ HC41	53 1/8	1348	13/32	10	9415	▼ HC50	41 7/8	1064	15/32	12
7530	▼ HC41	53 5/8	1361	13/32	10	9420	▼ HC50	42 3/8	1076	15/32	12
7535	▼ HC41	54 1/8	1374	13/32	10	9425	▼ HC50	42 7/8	1089	15/32	12
7541	▼ HC41	54 5/8	1386	13/32	10	9430	▼ HC50	43 3/8	1102	15/32	12
7545	▼ HC41	55 1/8	1399	13/32	10	9435	▼ HC50	43 7/8	1114	15/32	12
7550	▼ HC41	55 5/8	1412	13/32	10	9440	▼ HC50	44 3/8	1127	15/32	12
7555	▼ HC41	56 1/8	1425	13/32	10	9447	▼ HC50	44 7/8	1140	15/32	12
7560	▼ HC41	56 5/8	1437	13/32	10	9451	▼ HC50	45 3/8	1153	15/32	12
7565	▼ HC41	57 1/8	1450	13/32	10	9452M	▼ HC50MODIFIED	45 5/8	1158	17/32	13
7570	▼ HC41	57 5/8	1464	13/32	10	9453M	▼ HC50MODIFIED	45 3/4	1161	17/32	13
7575	▼ HC41	58 1/8	1476	13/32	10	9455	▼ HC50	45 7/8	1165	15/32	12
7580	▼ HC41	58 5/8	1488	13/32	10	9463	▼ HC50	46 3/8	1178	15/32	12
7585	▼ HC41	59 1/8	1501	13/32	10	9465	▼ HC50	46 7/8	1191	15/32	12
7590	▼ HC41	59 5/8	1513	13/32	10	9470	▼ HC50	47 3/8	1203	15/32	12
7597	▼ HC41	60 1/8	1526	13/32	10	9476	▼ HC50	47 7/8	1216	15/32	12
7603	▼ HC41	60 5/8	1539	13/32	10	9480	▼ HC50	48 3/8	1229	15/32	12
7612	▼ HC41	61 5/8	1564	13/32	10	9485	▼ HC50	48 7/8	1241	15/32	12
7619	▼ HC41	62 5/8	1590	13/32	10	9490	▼ HC50	49 3/8	1254	15/32	12
7625	▼ HC41	63 1/8	1602	13/32	10	9492M	▼ HC50MODIFIED	49 5/8	1259	19/32	15
7630	▼ HC41	63 5/8	1615	13/32	10	9495	▼ HC50	49 7/8	1267	15/32	12
7640	▼ HC41	64 5/8	1640	13/32	10	9500	▼ HC50	50 3/8	1280	15/32	12
7650	▼ HC41	65 5/8	1666	13/32	10	9505	▼ HC50	50 7/8	1292	15/32	12
7660	▼ HC41	66 5/8	1691	13/32	10	9510	▼ HC50	51 3/8	1305	15/32	12
7665	▼ HC41	67 1/8	1704	13/32	10	9520	▼ HC50	52 3/8	1330	15/32	12
7673	▼ HC41	67 5/8	1717	13/32	10	9525	▼ HC50	52 7/8	1343	15/32	12
7680	▼ HC41	68 5/8	1742	13/32	10	9530	▼ HC50	53 3/8	1356	15/32	12
7695	▼ HC41	70 1/8	1780	13/32	10	9540	▼ HC50	54 3/8	1381	15/32	12
7715	▼ HC41	72 1/8	1831	13/32	10	9545	▼ HC50	54 7/8	1394	15/32	12
7730	▼ HC41	73 5/8	1869	13/32	10	9550	▼ HC50	55 3/8	1407	15/32	12
7743	▼ HC41	74 5/8	1894	13/32	10	9551M	▼ HC50MODIFIED	55 1/2	1411	17/32	13
7760	▼ HC41	76 5/8	1945	13/32	10	9555	▼ HC50	55 7/8	1418	15/32	12
7775	▼ HC41	78 1/8	1983	13/32	10	9560	▼ HC50	56 3/8	1432	15/32	12
9245	▼ HC50	24 7/8	632	15/32	12	9565	▼ HC50	56 7/8	1445	15/32	12
9255	▼ HC50	25 7/8	657	15/32	12	9570	▼ HC50	57 3/8	1457	15/32	12
9260	▼ HC50	26 3/8	670	15/32	12	9580	▼ HC50	58 3/8	1483	15/32	12
9265	▼ HC50	26 7/8	683	15/32	12	9585	▼ HC50	58 7/8	1495	15/32	12
9270	▼ HC50	27 3/8	695	15/32	12	9590	▼ HC50	59 3/8	1508	15/32	12
9279	▼ HC50	28 1/4	718	15/32	12	9600	▼ HC50	60 3/8	1534	15/32	12
9290	▼ HC50	29 3/8	746	15/32	12	9605	▼ HC50	60 7/8	1546	15/32	12
9295	▼ HC50	29 7/8	759	15/32	12	9610	▼ HC50	61 3/8	1559	15/32	12
9300	▼ HC50	30 3/8	772	15/32	12	9620	▼ HC50	62 3/8	1584	15/32	12
9305	▼ HC50	30 7/8	784	15/32	12	9625	▼ HC50	62 7/8	1597	15/32	12
9309	▼ HC50	31 3/8	797	15/32	12	9630	▼ HC50	63 3/8	1610	15/32	12
9313	▼ HC50	31 7/8	809	15/32	12	9635	▼ HC50	63 7/8	1622	15/32	12
9319	▼ HC50	32 3/8	822	15/32	12	9640	▼ HC50	64 3/8	1635	15/32	12
9325	▼ HC50	32 7/8	835	15/32	12	9650	▼ HC50	65 3/8	1661	15/32	12
9330	▼ HC50	33 3/8	848	15/32	12	9660	▼ HC50	66 3/8	1686	15/32	12
9335	▼ HC50	33 7/8	860	15/32	12	9670	▼ HC50	67 3/8	1711	15/32	12
9341	▼ HC50	34 3/8	873	15/32	12	9680	▼ HC50	68 3/8	1737	15/32	12
9345	▼ HC50	34 7/8	886	15/32	12	9690	▼ HC50	69 3/8	1762	15/32	12
9348M	▼ HC50MODIFIED	35 1/4	895	17/32	13	9700	▼ HC50	70 3/8	1788	15/32	12
9350	▼ HC50	35 3/8	899	15/32	12	9710	▼ HC50	71 3/8	1813	15/32	12
9355	▼ HC50	35 7/8	911	15/32	12	9720	▼ HC50	72 3/8	1838	15/32	12
9360	▼ HC50	36 3/8	924	15/32	12	9730	▼ HC50	73 3/8	1864	15/32	12
9361M	▼ HC50MODIFIED	36 1/2	928	19/32	15	9740	▼ HC50	74 3/8	1889	15/32	12
9362M	▼ HC50MODIFIED	36 5/8	930	17/32	13	9745	▼ HC50	74 7/8	1902	15/32	12
9365	▼ HC50	36 7/8	937	15/32	12	9755	▼ HC50	75 7/8	1927	15/32	12
9370	▼ HC50	37 3/8	949	15/32	12	9765	▼ HC50	76 7/8	1953	15/32	12
9375	▼ HC50	37 7/8	962	15/32	12	9770	▼ HC50	77 3/8	1965	15/32	12
9378	▼ HC50	38 1/8	968	15/32	12	9775	▼ HC50	77 7/8	1978	15/32	12
9380	▼ HC50	38 3/8	975	15/32	12	9810	▼ HC50	81 3/8	2067	15/32	12
9385	▼ HC50	38 7/8	987	15/32	12	9820	▼ HC50	82 3/8	2092	15/32	12
9390	▼ HC50	39 3/8	1000	15/32	12	9830	▼ HC50	83 3/8	2118	15/32	12
9395	▼ HC50	39 7/8	1013	15/32	12	9840	▼ HC50	84 3/8	2143	15/32	12
9400	▼ HC50	40 3/8	1026	15/32	12	9850	▼ HC50	85 3/8	2169	15/32	12

▼ Notched Belt




## Showing Nominal Belt Top Widths and Outside Lengths with Our Corresponding Belt Numbers

IMPORTANT: Lengths shown (O.C. is Outside Circumference) are obtained by measuring around the outside of the belt. These lengths will not agree exactly with the size significant belt numbering system which is based on the effective length of the belt. Effective length ("engineered" length) cannot be measured in the field because special tools are required.

Automotive Top Widths are the standard sizes defined by the automotive belt industry (SAE J636). Due to manufacturing processes that create "Vertical Flats", the top width of XL and Truck/Bus series V-Belts will not agree with the printed top width dimensions. Top width on this page and on the belt sleeve refers to the pulley groove width and not the actual top width of these belts. A picture of a V-Belt with "Vertical Flats" is shown below. Actual top width of like belt sizes will also vary slightly depending on the manufacturer and belt style.



Competitive V-Belt

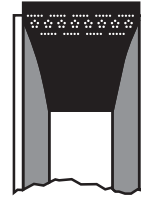

Our V-Belts with "Vertical Flats"

Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>1/4" (6 mm) Top Width (HC25)</b>			<b>13/32" (10 mm) Top Width (HC38 Mod)</b>			<b>13/32" (10 mm) Top Width (HC41) - Cont.</b>		
26 1/4	665	7261	45 1/4	1149	⊗ 7447M	40 1/8	1018	▼ 7395
28 3/8	720	7279				40 5/8	1031	▼ 7400
30 1/4	770	7298				41 1/8	1044	▼ 7405
31 1/4	795	7309				41 5/8	1056	▼ 7410
32 1/4	820	7318				42 1/8	1069	▼ 7417
33 1/4	845	7329				42 5/8	1082	▼ 7420
34 1/4	870	7333				43 1/8	1095	▼ 7425
35 1/4	895	7348	21 1/4	540	▼ 7208	43 5/8	1107	▼ 7430
36 1/4	920	7359	22 1/8	561	▼ 7215	44 1/8	1120	▼ 7435
36 3/4	935	7363	24 5/8	624	▼ 7240	44 5/8	1132	▼ 7440
38 1/4	970	7381	25 5/8	650	▼ 7250	45 1/8	1145	▼ 7445
39 1/4	995	7388	26 1/8	663	▼ 7255	45 3/8	1151	▼ 7448
41 1/4	1050	7409	26 5/8	675	▼ 7260	45 5/8	1158	▼ 7450
			27 1/8	688	▼ 7265	45 7/8	1164	▼ 7453
			27 5/8	701	▼ 7270	46 1/8	1171	▼ 7455
			28 5/8	726	▼ 7280	46 5/8	1183	▼ 7460
			29 5/8	751	▼ 7290	47 1/8	1196	▼ 7465
			29 7/8	758	▼ 7292	47 5/8	1209	▼ 7470
			30 1/8	764	▼ 7295	47 7/8	1215	▼ 7473
			30 5/8	777	▼ 7300	48 1/8	1221	▼ 7475
			31 1/8	792	▼ 7305	48 5/8	1234	▼ 7480
			31 5/8	802	▼ 7312	48 7/8	1242	▼ 7483
			32 1/8	815	▼ 7315	49 1/8	1247	▼ 7485
			32 5/8	828	▼ 7320	49 5/8	1260	▼ 7490
			33 1/8	840	▼ 7325	50 1/8	1272	▼ 7495
			33 3/8	847	▼ 7328	50 5/8	1285	▼ 7500
			33 5/8	853	▼ 7330	51 1/8	1297	▼ 7508
			34 1/8	866	▼ 7335	51 5/8	1310	▼ 7512
			34 5/8	878	▼ 7340	52 1/8	1323	▼ 7516
			35 1/8	891	▼ 7345	52 5/8	1336	▼ 7520
			35 5/8	904	▼ 7350	53 1/8	1348	▼ 7525
			36 1/8	919	▼ 7355	53 5/8	1361	▼ 7530
			36 5/8	929	▼ 7360	54 1/8	1374	▼ 7535
			37 1/8	942	▼ 7365	54 5/8	1386	▼ 7541
			37 5/8	954	▼ 7370	55 1/8	1399	▼ 7545
			38 1/8	967	▼ 7375	55 5/8	1412	▼ 7550
			38 5/8	980	▼ 7380	56 1/8	1425	▼ 7555
			39 1/8	993	▼ 7385	56 5/8	1437	▼ 7560
			39 5/8	1005	▼ 7390			

▼ Notched Belt    ⊗ Set of Two Belts



**XL® V-BELTS – LISTED BY SIZE**

Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>13/32" (10 mm) Top Width (HC41) - Cont.</b>			<b>15/32" (12 mm) Top Width (HC 50) - Cont.</b>			<b>15/32" (12 mm) Top Width (HC 50) - Cont.</b>		
57 1/8	1450	▼ 7565	35 3/8	899	▼ 9350	59 3/8	1508	▼ 9590
57 5/8	1464	▼ 7570	35 7/8	911	▼ 9355	60 3/8	1534	▼ 9600
58 1/8	1476	▼ 7575	36 3/8	924	▼ 9360	60 7/8	1546	▼ 9605
58 5/8	1488	▼ 7580	36 7/8	937	▼ 9365	61 3/8	1559	▼ 9610
59 1/8	1501	▼ 7585	37 3/8	949	▼ 9370	62 3/8	1584	▼ 9620
59 5/8	1513	▼ 7590	37 7/8	962	▼ 9375	62 7/8	1597	▼ 9625
60 1/8	1526	▼ 7597	38 1/8	968	▼ 9378	63 3/8	1610	▼ 9630
60 5/8	1539	▼ 7603	38 3/8	975	▼ 9380	63 7/8	1622	▼ 9635
61 5/8	1564	▼ 7612	38 7/8	987	▼ 9385	64 3/8	1635	▼ 9640
62 5/8	1590	▼ 7619	39 3/8	1000	▼ 9390	65 3/8	1661	▼ 9650
63 1/8	1602	▼ 7625	39 7/8	1013	▼ 9395	66 3/8	1686	▼ 9660
63 5/8	1615	▼ 7630	40 3/8	1026	▼ 9400	67 3/8	1711	▼ 9670
64 5/8	1640	▼ 7640	40 5/8	1032	▼ 9403	68 3/8	1737	▼ 9680
65 5/8	1666	▼ 7650	40 7/8	1038	▼ 9405	69 3/8	1762	▼ 9690
66 5/8	1691	▼ 7660	41 3/8	1051	▼ 9412	70 3/8	1788	▼ 9700
67 1/8	1704	▼ 7665	41 7/8	1064	▼ 9415	71 3/8	1813	▼ 9710
67 5/8	1717	▼ 7673	42 3/8	1076	▼ 9420	72 3/8	1838	▼ 9720
68 5/8	1742	▼ 7680	42 7/8	1089	▼ 9425	73 3/8	1864	▼ 9730
70 1/8	1780	▼ 7695	43 3/8	1102	▼ 9430	74 3/8	1889	▼ 9740
72 1/8	1831	▼ 7715	43 7/8	1114	▼ 9435	74 7/8	1902	▼ 9745
73 5/8	1869	▼ 7730	44 3/8	1127	▼ 9440	75 7/8	1927	▼ 9755
74 5/8	1894	▼ 7743	44 7/8	1140	▼ 9447	76 7/8	1953	▼ 9765
76 5/8	1945	▼ 7760	45 3/8	1153	▼ 9451	77 3/8	1965	▼ 9770
78 1/8	1983	▼ 7775	45 7/8	1165	▼ 9455	77 7/8	1978	▼ 9775
			46 3/8	1178	▼ 9463	81 3/8	2067	▼ 9810
			46 7/8	1191	▼ 9465	82 3/8	2092	▼ 9820
			47 3/8	1203	▼ 9470	83 3/8	2118	▼ 9830
			47 7/8	1216	▼ 9476	84 3/8	2143	▼ 9840
			48 3/8	1229	▼ 9480	85 3/8	2169	▼ 9850
			48 7/8	1241	▼ 9485			
			49 3/8	1254	▼ 9490	<b>17/32" (13 mm) Top Width (HC50 Mod)</b>		
			49 7/8	1267	▼ 9495	35 1/4	895	▼ 9348M
			50 3/8	1280	▼ 9500	36 5/8	930	▼ 9362M
			50 7/8	1292	▼ 9505	45 5/8	1158	▼ 9452M
			51 3/8	1305	▼ 9510	45 3/4	1161	▼ 9453M
			52 3/8	1330	▼ 9520	55 1/2	1411	▼ 9551M
			52 7/8	1343	▼ 9525			
			53 3/8	1356	▼ 9530	<b>19/32" (15 mm) Top Width (HC50 Mod)</b>		
			54 3/8	1381	▼ 9540	36 1/2	928	▼ 9361M
			54 7/8	1394	▼ 9545	49 5/8	1259	▼ 9492M
			55 3/8	1407	▼ 9550			
			55 7/8	1418	▼ 9555			
			56 3/8	1432	▼ 9560			
			56 7/8	1445	▼ 9565			
			57 3/8	1457	▼ 9570			
			58 3/8	1483	▼ 9580			
			58 7/8	1495	▼ 9585			

▼ Notched Belt




## Showing Belt Numbers with Corresponding Nominal Outside Lengths and Top Widths

IMPORTANT: Lengths shown (O.C. is Outside Circumference) are obtained by measuring around the outside of the belt. These lengths will not agree exactly with the size significant belt numbering system which is based on the effective length of the belt. Effective length (“engineered” length) cannot be measured in the field because special tools are required.

Automotive Top Widths are the standard sizes defined by the automotive belt industry (SAE J636). Due to manufacturing processes that create “Vertical Flats”, the top width of XL and Truck/Bus series V-Belts will not agree with the printed top width dimensions. Top width on this page and on the belt sleeve refers to the pulley groove width and not the actual top width of these belts. A picture of a V-Belt with “Vertical Flats” is shown below. Actual top width of like belt sizes will also vary slightly depending on the manufacturer and belt style.



Competitive V-Belt

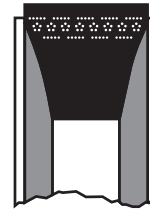

Our V-Belts with “Vertical Flats”

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
TR20412	41 5/8	1057	19/32	15	TR22607	61 1/4	1556	19/32	15
TR20426	43	1092	19/32	15	TR22625	63 1/8	1602	19/32	15
TR20451	45 1/2	1155	19/32	15	TR22635	64 1/8	1627	19/32	15
TR20544	54 3/4	1390	19/32	15	TR22648	65 1/4	1658	19/32	15
TR20619	62 3/8	1585	19/32	15	TR22657	66 1/4	1682	19/32	15
TR22299	30 1/2	774	19/32	15	TR22664	67	1703	19/32	15
TR22322	32 3/4	833	19/32	15	TR22676	68	1728	19/32	15
TR22329	33 1/2	850	19/32	15	TR22692	69 3/4	1773	19/32	15
TR22336	34 1/8	868	19/32	15	TR22711	71 5/8	1819	19/32	15
TR22344	34 7/8	886	19/32	15	TR22720	72 5/8	1844	19/32	15
TR22350	35 5/8	906	19/32	15	TR22752	75 3/4	1924	19/32	15
TR22358	36 1/2	926	19/32	15	TR22770	77 5/8	1971	19/32	15
TR22363	36 7/8	937	19/32	15	TR22792	79 5/8	2021	19/32	15
TR22373	38	964	19/32	15	TR24281	28 5/8	728	21/32	17
TR22380	38 5/8	980	19/32	15	TR24308	31 1/2	799	21/32	17
TR22386	39 1/8	993	19/32	15	TR24315	32	812	21/32	17
TR22392	39 3/4	1010	19/32	15	TR24355	36 1/8	918	21/32	17
TR22397	40 1/4	1022	19/32	15	TR24365	37 1/8	943	21/32	17
TR22401	40 5/8	1031	19/32	15	TR24379	38 1/2	978	21/32	17
TR22405	41 1/8	1045	19/32	15	TR24400	40 5/8	1032	21/32	17
TR22410	41 5/8	1056	19/32	15	TR24403	40 3/4	1036	21/32	17
TR22416	42 1/4	1073	19/32	15	TR24407	41 1/4	1047	21/32	17
TR22425	43 1/8	1095	19/32	15	TR24414	42	1067	21/32	17
TR22434	44	1117	19/32	15	TR24424	42 7/8	1090	21/32	17
TR22443	44 7/8	1139	19/32	15	TR24438	44 3/8	1126	21/32	17
TR22448	45 3/8	1151	19/32	15	TR24449	45 5/8	1158	21/32	17
TR22455	46 1/8	1171	19/32	15	TR24457	46 1/4	1174	21/32	17
TR22461	46 5/8	1185	19/32	15	TR24461	46 5/8	1183	21/32	17
TR22474	47 7/8	1218	19/32	15	TR24465	47	1195	21/32	17
TR22485	49 1/8	1247	19/32	15	TR24476	48 1/4	1225	21/32	17
TR22495	50 1/8	1273	19/32	15	TR24489	49 3/8	1255	21/32	17
TR22508	51 3/8	1306	19/32	15	TR24500	50 5/8	1285	21/32	17
TR22514	52	1320	19/32	15	TR24515	52	1320	21/32	17
TR22517	52 1/2	1334	19/32	15	TR24530	53 5/8	1362	21/32	17
TR22525	53 1/8	1349	19/32	15	TR24538	54 3/8	1380	21/32	17
TR22534	53 7/8	1369	19/32	15	TR24562	56 5/8	1438	21/32	17
TR22545	55 1/8	1399	19/32	15	TR24578	58 1/4	1480	21/32	17
TR22553	55 7/8	1420	19/32	15	TR24597	60 1/4	1530	21/32	17
TR22570	57 5/8	1462	19/32	15	TR24607	61 3/8	1560	21/32	17
TR22578	58 1/4	1479	19/32	15	TR24619	62 1/2	1589	21/32	17
TR22588	59 3/8	1509	19/32	15	TR24638	64 1/4	1631	21/32	17

All Green Stripe Truck and Bus V-Belts are Notched





## GREEN STRIPE® TRUCK AND BUS V-BELTS – LISTED BY NUMBER

Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)	Belt Number	Length (in.)	Length (mm)	Top Width (in.)	Top Width (mm)
TR24647	65 1/4	1658	21/32	17	TR28649	65 1/2	1663	25/32	20
TR24664	67	1702	21/32	17	TR28657	66 1/4	1684	25/32	20
TR24688	69 1/4	1759	21/32	17	TR28666	67 1/4	1710	25/32	20
TR24709	71 1/4	1810	21/32	17	TR28680	68 5/8	1744	25/32	20
TR26341	34 5/8	879	23/32	19	TR28693	69 7/8	1775	25/32	20
TR26353	6	913	23/32	19	TR28706	71 1/8	1807	25/32	20
TR26366	37 1/8	945	25/32	20	TR28733	73 7/8	1875	25/32	20
TR28333	33 7/8	859	25/32	20	TR28743	75	1905	25/32	20
TR28346	35 1/8	892	25/32	20	TR28786	79 1/8	2009	25/32	20
TR28376	38 1/4	971	25/32	20	TR30408	41 1/2	1054	7/8	22
TR28386	39 1/4	996	25/32	20	TR30428	43 1/2	1104	7/8	22
TR28390	39 5/8	1007	25/32	20	TR30448	45 3/8	1152	7/8	22
TR28400	40 5/8	1032	25/32	20	TR30467	47 1/4	1201	7/8	22
TR28406	41 1/8	1046	25/32	20	TR30484	49	1244	7/8	22
TR28412	41 7/8	1062	25/32	20	TR30506	51 1/8	1299	7/8	22
TR28423	42 7/8	1088	25/32	20	TR30537	54 1/8	1375	7/8	22
TR28429	43 1/2	1105	25/32	20	TR30543	54 7/8	1393	7/8	22
TR28437	44 1/4	1125	25/32	20	TR30589	59 1/2	1510	7/8	22
TR28445	45 1/8	1145	25/32	20	TR30624	62 7/8	1599	7/8	22
TR28454	45 7/8	1166	25/32	20	TR30652	65 3/4	1671	7/8	22
TR28463	46 7/8	1190	25/32	20	TR30672	67 3/4	1721	7/8	22
TR28473	47 7/8	1216	25/32	20	TR30698	70 3/8	1788	7/8	22
TR28480	48 5/8	1235	25/32	20	TR30710	71 5/8	1818	7/8	22
TR28483	48 7/8	1240	25/32	20	TR30722	72 3/4	1849	7/8	22
TR28492	49 7/8	1267	25/32	20	TR30754	75 3/4	1925	7/8	22
TR28498	50 1/4	1277	25/32	20	TR30770	77	1955	7/8	22
TR28501	50 7/8	1291	25/32	20	TR30808	81 1/4	2065	7/8	22
TR28510	51 5/8	1311	25/32	20	TR32491	49 3/4	1265	29/32	23
TR28514	52	1320	25/32	20	TR32513	51 7/8	1317	29/32	23
TR28522	52 7/8	1342	25/32	20	TR32571	57 5/8	1465	29/32	23
TR28545	55 1/8	1401	25/32	20	TR34435	43 7/8	1115	1	25
TR28550	55 5/8	1413	25/32	20	TR34456	46 1/8	1172	1	25
TR28557	56 1/4	1430	25/32	20	TR34467	47 1/4	1199	1	25
TR28565	57 1/8	1451	25/32	20	TR34495	49 7/8	1265	1	25
TR28570	57 5/8	1464	25/32	20	TR34506	51 1/8	1300	1	25
TR28575	58 1/8	1477	25/32	20	TR34545	55	1395	1	25
TR28583	58 7/8	1495	25/32	20	TR34604	61 1/8	1553	1	25
TR28596	60 1/4	1530	25/32	20	TR34700	70 5/8	1793	1	25
TR28616	62 1/4	1580	25/32	20	TR34711	71 5/8	1820	1	25
TR28628	63 3/8	1609	25/32	20	TR34771	77 3/4	1975	1	25

All Green Stripe Truck and Bus V-Belts are Notched




## Showing Nominal Belt Top Widths and Outside Lengths with Our Corresponding Belt Numbers

**IMPORTANT:** Lengths shown (O.C. is Outside Circumference) are obtained by measuring around the outside of the belt. These lengths will not agree exactly with the size significant belt numbering system which is based on the effective length of the belt. Effective length (“engineered” length) cannot be measured in the field because special tools are required.

Automotive Top Widths are the standard sizes defined by the automotive belt industry (SAE J636). Due to manufacturing processes that create “Vertical Flats”, the top width of XL and Truck/Bus series V-Belts will not agree with the printed top width dimensions. Top width on this page and on the belt sleeve refers to the pulley groove width and not the actual top width of these belts. A picture of a V-Belt with “Vertical Flats” is shown below. Actual top width of like belt sizes will also vary slightly depending on the manufacturer and belt style.



Competitive V-Belt

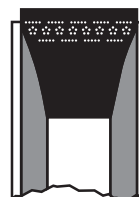

Our V-Belts with “Vertical Flats”

Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>19/32” (15 mm) Top Width</b>			<b>19/32” (15 mm) Top Width - Cont.</b>			<b>21/32” (17 mm) Top Width - Cont.</b>		
30 1/2	774	TR22299	62 3/8	1585	TR20619	60 1/4	1530	TR24597
32 3/4	833	TR22322	63 1/8	1602	TR22625	61 3/8	1560	TR24607
33 1/2	850	TR22329	64 1/8	1627	TR22635	62 1/2	1589	TR24619
34 1/8	868	TR22336	65 1/4	1658	TR22648	64 1/4	1631	TR24638
34 7/8	886	TR22344	66 1/4	1682	TR22657	65 1/4	1658	TR24647
35 5/8	906	TR22350	67	1703	TR22664	67	1702	TR24664
36 1/2	926	TR22358	68	1728	TR22676	69 1/4	1759	TR24688
36 7/8	937	TR22363	69 3/4	1773	TR22692	71 1/4	1810	TR24709
38	964	TR22373	71 5/8	1819	TR22711	<b>23/32” (19 mm) Top Width</b>		
38 5/8	980	TR22380	72 5/8	1844	TR22720	34 5/8	879	TR26341
39 1/8	993	TR22386	75 3/4	1924	TR22752	36	913	TR26353
39 3/4	1010	TR22392	77 5/8	1971	TR22770	<b>25/32” (20 mm) Top Width</b>		
40 1/4	1022	TR22397	79 5/8	2021	TR22792	33 7/8	859	TR28333
40 5/8	1031	TR22401	<b>21/32” (17 mm) Top Width</b>			35 1/8	892	TR28346
41 1/8	1045	TR22405	28 5/8	728	TR24281	37 1/8	945	TR26366
41 5/8	1056	TR22410	31 1/2	799	TR24308	38 1/4	971	TR28376
41 5/8	1057	TR20412	32	812	TR24315	39 1/4	996	TR28386
42 1/4	1073	TR22416	36 1/8	918	TR24355	39 5/8	1007	TR28390
43	1092	TR20426	37 1/8	943	TR24365	40 5/8	1032	TR28400
43 1/8	1095	TR22425	38 1/2	978	TR24379	41 1/8	1046	TR28406
44	1117	TR22434	40 5/8	1032	TR24400	41 7/8	1062	TR28412
44 7/8	1139	TR22443	40 3/4	1036	TR24403	42 7/8	1088	TR28423
45 3/8	1151	TR22448	41 1/4	1047	TR24407	43 1/2	1105	TR28429
45 1/2	1155	TR20451	42	1067	TR24414	44 1/4	1125	TR28437
46 1/8	1171	TR22455	42 7/8	1090	TR24424	45 1/8	1145	TR28445
46 5/8	1185	TR22461	44 3/8	1126	TR24438	45 7/8	1166	TR28454
47 7/8	1218	TR22474	45 5/8	1158	TR24449	46 7/8	1190	TR28463
49 1/8	1247	TR22485	46 1/4	1174	TR24457	47 7/8	1216	TR28473
50 1/8	1273	TR22495	46 5/8	1183	TR24461	48 5/8	1235	TR28480
51 3/8	1306	TR22508	47	1195	TR24465	48 7/8	1240	TR28483
52	1320	TR22514	48 1/4	1225	TR24476	49 7/8	1267	TR28492
52 1/2	1334	TR22517	49 3/8	1255	TR24489	50 1/4	1277	TR28498
53 1/8	1349	TR22525	50 5/8	1285	TR24500	50 7/8	1291	TR28501
53 7/8	1369	TR22534	52	1320	TR24515	51 5/8	1311	TR28510
54 3/4	1390	TR20544	53 5/8	1362	TR24530	52	1320	TR28514
55 1/8	1399	TR22545	54 3/8	1380	TR24538	52 7/8	1342	TR28522
55 7/8	1420	TR22553	56 5/8	1438	TR24562			
57 5/8	1462	TR22570	58 1/4	1480	TR24578			
58 1/4	1479	TR22578						
59 3/8	1509	TR22588						
61 1/4	1556	TR22607						

All Gold Stripe Truck and Bus V-Belts are Notched



## GREEN STRIPE® TRUCK AND BUS V-BELTS – LISTED BY SIZE

Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>25/32" (20 mm) Top Width - Cont.</b>			<b>7/8" (22 mm) Top Width</b>			<b>29/32" (23 mm) Top Width</b>		
55 1/8	1401	TR28545	41 1/2	1054	TR30408	49 3/4	1265	TR32491
55 5/8	1413	TR28550	43 1/2	1104	TR30428	51 7/8	1317	TR32513
56 1/4	1430	TR28557	45 3/8	1152	TR30448	57 5/8	1465	TR32571
57 1/8	1451	TR28565	47 1/4	1201	TR30467	<b>1" (25 mm) Top Width</b>		
57 5/8	1464	TR28570	49	1244	TR30484	43 7/8	1115	TR34435
58 1/8	1477	TR28575	51 1/8	1299	TR30506	46 1/8	1172	TR34456
58 7/8	1495	TR28583	54 1/8	1375	TR30537	47 1/4	1199	TR34467
60 1/4	1530	TR28596	54 7/8	1393	TR30543	49 7/8	1265	TR34495
62 1/4	1580	TR28616	59 1/2	1510	TR30589	51 1/8	1300	TR34506
63 3/8	1609	TR28628	62 7/8	1599	TR30624	55	1395	TR34545
65 1/2	1663	TR28649	65 3/4	1671	TR30652	61 1/8	1553	TR34604
66 1/4	1684	TR28657	67 3/4	1721	TR30672	70 5/8	1793	TR34700
67 1/4	1710	TR28666	70 3/8	1788	TR30698	71 5/8	1820	TR34711
68 5/8	1744	TR28680	71 5/8	1818	TR30710	77 3/4	1975	TR34771
69 7/8	1775	TR28693	72 3/4	1849	TR30722			
71 1/8	1807	TR28706	75 3/4	1925	TR30754			
73 7/8	1875	TR28733	77	1955	TR30770			
75	1905	TR28743	81 1/4	2065	TR30808			
79 1/8	2009	TR28786						


All Gold Stripe Truck and Bus V-Belts are Notched



## Showing Belt Numbers with Corresponding Nominal Outside Lengths and Top Widths per Strand

IMPORTANT: Lengths shown (O.C. is Outside Circumference) are obtained by measuring around the outside of the belt. These lengths will not agree exactly with the size significant belt numbering system which is based on the effective length of the belt. Effective length ("engineered" length) cannot be measured in the field because special tools are required.

Automotive Top Widths are the standard sizes defined by the automotive belt industry (SAE J636). Due to manufacturing processes that create "Vertical Flats", the top width of XL and Truck/Bus series V-Belts will not agree with the printed top width dimensions. Top width on this page and on the belt sleeve refers to the pulley groove width and not the actual top width of these belts. A picture of a V-Belt with "Vertical Flats" is shown below. Actual top width of like belt sizes will also vary slightly depending on the manufacturer and belt style.

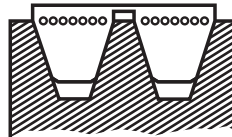


Belt Number	Length (in.)	Length (mm)	Top Width Per Strand (in.)	Top Width Per Strand (mm)	Template	Belt Number	Length (in.)	Length (mm)	Top Width Per Strand (in.)	Top Width Per Strand (mm)	Template
2/9305PB.....	31 1/2	799	1/2	13	YELLOW	2/9650PB.....	65 7/8	1673	1/2	13	YELLOW
2/9313PB.....	32 1/8	817	1/2	13	YELLOW	2/9660PB.....	66 7/8	1698	1/2	13	YELLOW
2/9325PB.....	33 1/2	852	1/2	13	YELLOW	2/9670PB.....	67 3/8	1710	1/2	13	YELLOW
2/9430PB.....	43 7/8	1116	1/2	13	YELLOW	2/9690PB.....	70	1778	1/2	13	YELLOW
2/9435PB.....	44 3/8	1128	1/2	13	YELLOW	2/9700PB.....	70 7/8	1800	1/2	13	YELLOW
2/9447PB.....	45 3/8	1154	1/2	13	YELLOW	2/9710PB.....	71 7/8	1825	1/2	13	YELLOW
2/9451PB.....	45 7/8	1164	1/2	13	YELLOW	2/9720PB.....	72 7/8	1850	1/2	13	YELLOW
2/9463PB.....	47	1195	1/2	13	YELLOW	2/9730PB.....	74	1879	1/2	13	YELLOW
2/9470PB.....	47 7/8	1217	1/2	13	YELLOW	2/TR22517PB.....	52 1/2	1330	11/16	17	GREEN
2/9476PB.....	48 3/8	1230	1/2	13	YELLOW	2/TR22553PB.....	56 1/4	1430	11/16	17	GREEN
2/9485FPB.....	49 5/8	1259	1/2	13	PINK	2/TR22570PB.....	58	1472	11/16	17	GREEN
2/9490PB.....	50	1270	1/2	13	YELLOW	2/TR28400PB.....	41	1041	7/8	22	RED
2/9500PB.....	50 3/4	1290	1/2	13	YELLOW	2/TR28411PB.....	41 3/4	1061	7/8	22	RED
2/9510PB.....	52	1321	1/2	13	YELLOW	2/TR28429PB.....	44 1/8	1120	7/8	22	RED
2/9520PB.....	53	1346	1/2	13	YELLOW	2/TR28437PB.....	44 1/4	1125	7/8	22	RED
2/9530PB.....	54	1373	1/2	13	YELLOW	2/TR28466PB.....	47 1/8	1198	7/8	22	RED
2/9540PB.....	54 3/4	1390	1/2	13	YELLOW	2/TR28473PB.....	48 1/4	1226	7/8	22	RED
2/9545PB.....	55 3/8	1405	1/2	13	YELLOW	2/TR28480PB.....	49	1244	7/8	22	RED
2/9550PB.....	56	1424	1/2	13	YELLOW	2/TR28483PB.....	49 1/8	1248	7/8	22	RED
2/9555PB.....	56 1/2	1435	1/2	13	YELLOW	2/TR28492PB.....	50 3/8	1279	7/8	22	RED
2/9570PB.....	58	1474	1/2	13	YELLOW	2/TR28501PB.....	51 1/8	1299	7/8	22	RED
2/9580PB.....	58	1473	1/2	13	-	2/TR28510PB.....	51 5/8	1310	7/8	22	RED
2/9590PB.....	59 7/8	1521	1/2	13	YELLOW	3/9470PB.....	47 7/8	1217	1/2	13	-
2/9600PB.....	60 5/8	1540	1/2	13	YELLOW	3/9500PB.....	50 5/8	1286	1/2	13	-
2/9610PB.....	61 7/8	1571	1/2	13	YELLOW	3/9525PB.....	53 1/4	1354	1/2	13	-
2/9640PB.....	64 3/8	1635	1/2	13	YELLOW	3/9530PB.....	54	1372	1/2	13	-



## Showing Nominal Belt Top Widths per Strand and Outside Lengths with Our Corresponding Belt Numbers

IMPORTANT: Lengths shown (O.C. is Outside Circumference) are obtained by measuring around the outside of the belt. These lengths will not agree exactly with the size significant belt numbering system which is based on the effective length of the belt. Effective length ("engineered" length) cannot be measured in the field because special tools are required.

Automotive Top Widths are the standard sizes defined by the automotive belt industry (SAE J636). Due to manufacturing processes that create "Vertical Flats", the top width of XL and Truck/Bus series V-Belts will not agree with the printed top width dimensions. Top width on this page and on the belt sleeve refers to the pulley groove width and not the actual top width of these belts. A picture of a V-Belt with "Vertical Flats" is shown below. Actual top width of like belt sizes will also vary slightly depending on the manufacturer and belt style.

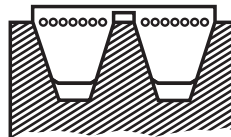

Length (in.)	Length (mm)	Template	Belt Number	Length (in.)	Length (mm)	Template	Belt Number	Length (in.)	Length (mm)	Template	Belt Number
<b>1/2" 913 mm) Top Width Per Strand</b>				<b>1/2" 913 mm) Top Width Per Strand - Cont.</b>				<b>11/16" (17 mm) Top Width Per Strand</b>			
31 1/2	799	YELLOW	2/9305PB	54	1372	-	3/9530PB	52 1/2	1330	GREEN	2/TR22517PB
32 1/8	817	YELLOW	2/9313PB	54 3/4	1390	YELLOW	2/9540PB	56 1/4	1430	GREEN	2/TR22553PB
33 1/2	852	YELLOW	2/9325PB	55 3/8	1405	YELLOW	2/9545PB	58	1472	GREEN	2/TR22570PB
43 7/8	1116	YELLOW	2/9430PB	56	1424	YELLOW	2/9550PB	<b>7/8" 922 mm) Top Width Per Strand</b>			
44 3/8	1128	YELLOW	2/9435PB	56 1/2	1435	YELLOW	2/9555PB	41	1041	RED	2/TR28400PB
45 3/8	1154	YELLOW	2/9447PB	58	1474	YELLOW	2/9570PB	41 3/4	1061	RED	2/TR28411PB
45 7/8	1164	YELLOW	2/9451PB	58	1473	-	2/9580PB	44 1/8	1120	RED	2/TR28429PB
47	1195	YELLOW	2/9463PB	59 7/8	1521	YELLOW	2/9590PB	44 1/4	1125	RED	2/TR28437PB
47 7/8	1217	YELLOW	2/9470PB	60 5/8	1540	YELLOW	2/9600PB	47 1/8	1198	RED	2/TR28466PB
47 7/8	1217	-	3/9470PB	61 7/8	1571	YELLOW	2/9610PB	48 1/4	1226	RED	2/TR28473PB
48 3/8	1230	YELLOW	2/9476PB	64 3/8	1635	YELLOW	2/9640PB	49	1244	RED	2/TR28480PB
49 5/8	1259	PINK	2/9485FPB	65 7/8	1673	YELLOW	2/9650PB	49 1/8	1248	RED	2/TR28483PB
50	1270	YELLOW	2/9490PB	66 7/8	1698	YELLOW	2/9660PB	50 3/8	1279	RED	2/TR28492PB
50 5/8	1286	-	3/9500PB	67 3/8	1710	YELLOW	2/9670PB	51 1/8	1299	RED	2/TR28501PB
50 3/4	1290	YELLOW	2/9500PB	70	1778	YELLOW	2/9690PB	51 5/8	1310	RED	2/TR28510PB
52	1321	YELLOW	2/9510PB	70 7/8	1800	YELLOW	2/9700PB				
53	1346	YELLOW	2/9520PB	71 7/8	1825	YELLOW	2/9710PB				
53 1/4	1354	-	3/9525PB	72 7/8	1850	YELLOW	2/9720PB				
54	1373	YELLOW	2/9530PB	74	1879	YELLOW	2/9730PB				






## Showing Hi-Power® II Belts with Corresponding Top Widths and Nominal Outside Lengths

PLEASE NOTE: V-Belt drives which use the belt as a clutch requires special consideration because the heat generated by belt slip (during engagement and disengagement) on some clutching applications can cause the V-Belt tensile materials in the belts listed below to shrink in length. The shrinkage may cause a belt, which is already engaged and driving, to not de-clutch, or a de-clutched belt may engage itself and start driving the machine unexpectedly. Depending on the machine and circumstances, either situation could prove dangerous to the machine operator or bystanders.

Belts especially designed to minimize or eliminate heat shrinkage may be required.

IMPORTANT: The outside length is determined by placing a steel tape around the outside of the belt. This method should be used because it is the one most commonly used by Dealers and Jobbers when measuring a belt.

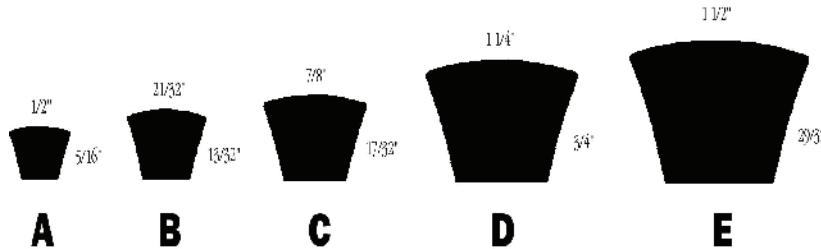

Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)
<b>A Section</b>		<b>A Section - Cont.</b>		<b>A Section - Cont.</b>		<b>B Section - Cont.</b>		<b>B Section - Cont.</b>	
A24.....	26	A64.....	66	A105.....	107	B40.....	43	B81.....	84
A25.....	27	AP64.....	+ 66	A106.....	108	B41.....	44	B82.....	85
A26.....	28	A65.....	67	A107.....	109	B42.....	45	B83.....	86
A27.....	29	A66.....	68	A108.....	110	B43.....	46	B84.....	87
A28.....	30	A67.....	69	A110.....	112	B44.....	47	B85.....	88
A29.....	31	A68.....	70	A112.....	114	B45.....	48	B86.....	89
A29.8.....	31 13/16	A69.....	71	A113.....	115	B46.....	49	B87.....	90
A30.....	32	A70.....	72	A114.....	116	B47.....	50	B88.....	91
A31.....	33	A71.....	73	A115.....	117	B48.....	51	B89.....	92
A32.....	34	A72.....	74	A116.....	118	B49.....	52	B90.....	93
A33.....	35	A73.....	75	A117.....	119	B50.....	53	B91.....	94
A34.....	36	A74.....	76	A118.....	120	B51.....	54	B92.....	95
A35.....	37	A75.....	77	A120.....	122	B52.....	55	B93.....	96
A36.....	38	A76.....	78	A124.....	126	B53.....	56	B94.....	97
A37.....	39	A77.....	79	A128.....	130	B54.....	57	B95.....	98
A38.....	40	A78.....	80	A130.....	132	B55.....	58	BP95.....	+ 98
A39.....	41	A79.....	81	A132.....	134	B56.....	59	B96.....	99
A40.....	42	A80.....	82	A133.....	135	B57.....	60	B97.....	100
A41.....	43	A81.....	83	A134.....	136	B58.....	61	B98.....	101
A42.....	44	A82.....	84	A136.....	138	B59.....	62	B99.....	102
A43.....	45	A83.....	85	A140.....	142	B60.....	63	B100.....	103
A44.....	46	A84.....	86	A144.....	146	B61.....	64	BP100.....	+ 103
A45.....	47	A85.....	87	A148.....	150	B62.....	65	B101.....	104
A46.....	48	A86.....	88	A158.....	160	B63.....	66	B102.....	105
A47.....	49	A87.....	89	A173.....	175	B64.....	67	B103.....	106
A48.....	50	A88.....	90	A180.....	182	B65.....	68	B104.....	107
A49.....	51	A89.....	91	<b>B Section</b>		B66.....	69	B105.....	108
A50.....	52	A90.....	92			B67.....	70	B106.....	109
A51.....	53	A91.....	93	B28.....	31	B68.....	71	B107.....	110
A52.....	54	A92.....	94	B29.....	32	B69.....	72	B108.....	111
A53.....	55	A93.....	95	B30.....	33	B70.....	73	BP108.....	+ 111
A54.....	56	A94.....	96	B31.....	34	B71.....	74	B109.....	112
A55.....	57	A95.....	97	B32.....	35	B72.....	75	B110.....	113
A56.....	58	A96.....	98	B33.....	36	B73.....	76	B111.....	114
A57.....	59	A97.....	99	B34.....	37	B74.....	77	B112.....	115
A58.....	60	A98.....	100	B35.....	38	B75.....	78	B113.....	116
A59.....	61	A99.....	101	B36.....	39	B76.....	79	B114.....	117
A60.....	62	A100.....	102	B37.....	40	B77.....	80	B115.....	118
A61.....	63	A101.....	103	B38.....	41	B78.....	81	B116.....	119
A62.....	64	A102.....	104	B39.....	42	B79.....	82	B117.....	120
A63.....	65	A103.....	105			B80.....	83	B118.....	121

+ Aramid Cord




# HI-POWER® II V-BELTS – LISTED BY NUMBER

Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)
<b>B Section - Cont.</b>		<b>B Section - Cont.</b>		<b>C Section - Cont.</b>		<b>C Section - Cont.</b>		<b>D Section - Cont.</b>	
B120.....	123	B199.....	202	C84.....	88	C151.....	155	D195.....	200
B122.....	125	B205.....	208	C85.....	89	C152.....	156 3/4	D210.....	215
B123.....	126	B210.....	213	C86.....	90	C156.....	160	D225.....	228
B124.....	127	B225.....	226	C87.....	91	C158.....	162	D240.....	243
B126.....	129	B230.....	231	C90.....	94	C162.....	166	D255.....	258
B127.....	130	B240.....	241	C92.....	96	C170.....	174	D270.....	273
B128.....	131	B255.....	256	C93.....	97	C173.....	177	D285.....	288
B130.....	133	B270.....	271	C95.....	99	C180.....	184	D300.....	303
B131.....	134	B285.....	286	C96.....	100	C190.....	194	D315.....	318
B132.....	135	B300.....	301	C97.....	101	C195.....	199	D330.....	333
B133.....	136	B315.....	316	C98.....	102	C210.....	214	D345.....	348
B134.....	137	<b>C Section</b>		C99.....	103	C225.....	227	D360.....	363
B135.....	138	C48.....	52	C100.....	104	C240.....	242	D390.....	393
B136.....	139	C50.....	54	C101.....	105	C255.....	257	D420.....	423
B138.....	141	C51.....	55	C103.....	107	C270.....	272	D450.....	453
B139.....	142	C53.....	57	C105.....	109	C285.....	287	D480.....	483
B140.....	143	C54.....	58	CP105.....	+ 109	C300.....	302	D540.....	543
B142.....	145	C55.....	59	C106.....	110	C315.....	317	D600.....	603
B143.....	146	C57.....	61	C107.....	111	C330.....	332	D660.....	663
B144.....	147	C60.....	64	C108.....	112	C345.....	347	<b>E Section</b>	
B146.....	149	C62.....	66	C109.....	113	C360.....	362	E180.....	187
B147.....	150	C63.....	67	C110.....	114	C390.....	392	E195.....	202
B148.....	151	C65.....	69	C111.....	115	C420.....	422	E210.....	217
B150.....	153	C67.....	71	C112.....	116	<b>D Section</b>		E240.....	244
B152.....	155	C68.....	72	C115.....	119	D100.....	105	E270.....	274
B154.....	157	C70.....	74	C116.....	120	D105.....	110	E300.....	304
B156.....	159	C71.....	75	C120.....	124	D112.....	117	E330.....	334
B158.....	161	C72.....	76	C122.....	126	D120.....	125	E360.....	364
B162.....	165	C73.....	77	C124.....	128	D128.....	133	E390.....	394
B166.....	169	C75.....	79	C126.....	130	D136.....	141	E420.....	424
B168.....	171	C77.....	81	C128.....	132	D144.....	149	E480.....	484
B173.....	176	C78.....	82	C130.....	134	D158.....	163	E540.....	544
B180.....	183	C79.....	83	C136.....	140	D162.....	167	E600.....	604
B188.....	191	C80.....	84	C140.....	144	D173.....	178	E660.....	664
B190.....	193	C81.....	85	C144.....	148	D180.....	185		
B192.....	195	C83.....	87	C148.....	152				
B195.....	198			C150.....	154				

+ Aramid Cord






## Key to Size Numbering System

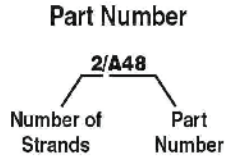

The part number is constructed by placing the number of strands required followed by a slash in front of the size.

In the example above **2/** is the number of strands, **A48** is the belt size.

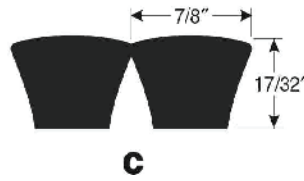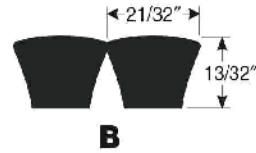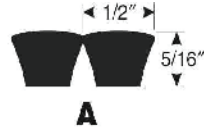


Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)
<b>A Section</b>		<b>B Section - Cont.</b>		<b>B Section - Cont.</b>	
2/A36.....	38	2/B68.....	71	2/B101.....	104
2/A48.....	50	2/B75.....	78	2/B148.....	151
2/A74.....	76	2/B80.....	83	2/B162.....	165
3/A55.....	57	2/B85.....	88	3/B81.....	84
3/A85.....	87	2/B86.....	89	<b>C Section</b>	
<b>B Section</b>		2/B90.....	93	2/C90.....	94
2/B61.....	64	2/B92.....	95		
2/B64.....	67	2/B93.....	96		
		2/B95.....	98		
		2/B99.....	102		






## Key to Size Numbering System

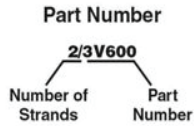

The part number is constructed by placing the number of strands required followed by a slash in front of the size.

In the example above 2/ is the number of strands, 3V600 is the belt size.

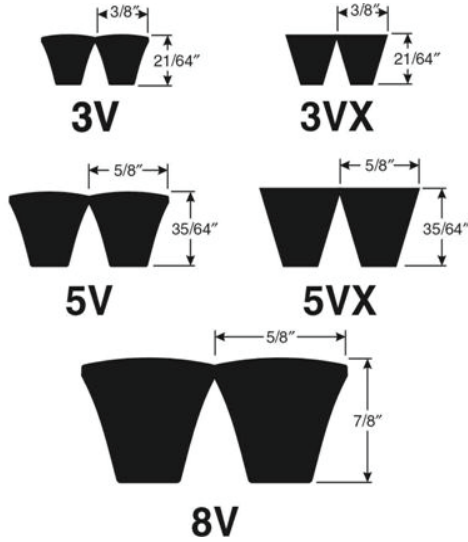

Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)
<b>3V/3VX Section</b>		<b>5V/5VX Section</b>		<b>5V/5VX Section - Cont.</b>		<b>5V/5VX Section - Cont.</b>	
2/3V600.....	60	2/5V950.....	95	2/5VX850.....	85	2/5VX1075.....	108 1/8
2/3VX375.....	37 1/2	2/5V975.....	97 1/2	2/5VX917.....	91 3/4	2/5VX1400.....	140
2/3VX475.....	47 1/2	2/5V1020.....	102	2/5VX930.....	93	3/5VP213.68.....	213 11/16
2/3VX500.....	50	2/5VX560.....	56	2/5VX950.....	95	3/5VP2000.....	200
2/3VX630.....	63	2/5VX600.....	60	2/5VX1000.....	100	5/5VX800.....	80
3/3V879.....	87 27/32	2/5VX670.....	67	2/5VX1042.....	105 1/4		
3/3V910.....	91	2/5VX686.....	69 1/4				
3/3VX500.....	50	2/5VX710.....	71				
3/3VX560.....	56	2/5VX800.....	80				
4/3VX425.....	42 1/2	2/5VX830.....	83				





## Showing Tri-Power® Belts with Corresponding Top Widths and Outside Lengths

PLEASE NOTE: V-Belt drives which use the belt as a clutch requires special consideration because the heat generated by belt slip (during engagement and disengagement) on some clutching applications can cause the V-Belt tensile materials in the belts listed below to shrink in length. The shrinkage may cause a belt, which is already engaged and driving, to not de-clutch, or a de-clutched belt may engage itself and start driving the machine unexpectedly. Depending on the machine and circumstances, either situation could prove dangerous to the machine operator or bystanders.

Belts especially designed to minimize or eliminate heat shrinkage may be required.

IMPORTANT: The outside length is determined by placing a steel tape around the outside of the belt. This method should be used because it is the one most commonly used by Dealers and Jobbers when measuring a belt.



Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)	Belt Number	Length (in.)
<b>AX SECTION</b>		<b>AX SECTION - Cont.</b>		<b>BX SECTION - Cont.</b>		<b>BX SECTION - Cont.</b>		<b>BX SECTION - Cont.</b>	
AX21.....	23	AX66.....	68	BX35.....	38	BX80.....	83	BX255.....	257
AX22.....	24	AX67.....	69	BX36.....	39	BX81.....	84	BX270.....	272
AX23.....	25	AX68.....	70	BX37.....	40	BX82.....	85	BX300.....	302
AX24.....	26	AX69.....	71	BX38.....	41	BX83.....	86	<b>CX SECTION</b>	
AX25.....	27	AX70.....	72	BX40.....	43	BX84.....	87	CX51.....	55
AX26.....	28	AX71.....	73	BX41.....	44	BX85.....	88	CX60.....	64
AX27.....	29	AX72.....	74	BX42.....	45	BX86.....	89	CX68.....	72
AX28.....	30	AX73.....	75	BX43.....	46	BX87.....	90	CX75.....	79
AX29.....	31	AX74.....	76	BX44.....	47	BX88.....	91	CX81.....	85
AX30.....	32	AX75.....	77	BX45.....	48	BX89.....	92	CX85.....	89
AX31.....	33	AX76.....	78	BX46.....	49	BX90.....	93	CX90.....	94
AX32.....	34	AX77.....	79	BX47.....	50	BX91.....	94	CX96.....	100
AX33.....	35	AX78.....	80	BX48.....	51	BX92.....	95	CX100.....	104
AX34.....	36	AX79.....	81	BX49.....	52	BX93.....	96	CX101.....	105
AX35.....	37	AX80.....	82	BX50.....	53	BX94.....	97	CX105.....	109
AX36.....	38	AX81.....	83	BX51.....	54	BX95.....	98	CX106.....	110
AX37.....	39	AX82.....	84	BX52.....	55	BX96.....	99	CX109.....	113
AX38.....	40	AX85.....	87	BX53.....	56	BX97.....	100	CX112.....	116
AX39.....	41	AX86.....	88	BX54.....	57	BX99.....	102	CX115.....	119
AX40.....	42	AX87.....	89	BX55.....	58	BX100.....	103	CX120.....	124
AX41.....	43	AX88.....	90	BX56.....	59	BX103.....	106	CX123.....	127
AX42.....	44	AX90.....	92	BX57.....	60	BX105.....	108	CX128.....	132
AX43.....	45	AX91.....	93	BX58.....	61	BX108.....	111	CX133.....	137
AX44.....	46	AX92.....	94	BX59.....	62	BX112.....	115	CX136.....	140
AX45.....	47	AX93.....	95	BX60.....	63	BX113.....	116	CX144.....	148
AX46.....	48	AX94.....	96	BX61.....	64	BX115.....	118	CX150.....	154
AX47.....	49	AX96.....	98	BX62.....	65	BX116.....	119	CX158.....	162
AX48.....	50	AX97.....	99	BX63.....	66	BX120.....	123	CX162.....	166
AX49.....	51	AX98.....	100	BX64.....	67	BX124.....	127	CX173.....	177
AX50.....	52	AX103.....	105	BX65.....	68	BX128.....	131	CX180.....	184
AX51.....	53	AX105.....	107	BX66.....	69	BX133.....	136	CX187.....	191
AX52.....	54	AX110.....	112	BX67.....	70	BX136.....	139	CX190.....	194
AX53.....	55	AX112.....	114	BX68.....	71	BX140.....	143	CX195.....	199
AX54.....	56	AX120.....	122	BX69.....	72	BX144.....	147	CX210.....	214
AX55.....	57	AX128.....	130	BX70.....	73	BX150.....	153	CX225.....	227
AX56.....	58	AX144.....	146	BX71.....	74	BX158.....	161	CX240.....	242
AX57.....	59	AX173.....	175	BX72.....	75	BX162.....	165	CX255.....	257
AX58.....	60	<b>BX SECTION</b>		BX73.....	76	BX173.....	176	CX270.....	272
AX59.....	61	BX28.....	31	BX74.....	77	BX180.....	183	CX300.....	302
AX60.....	62	BX31.....	34	BX75.....	78	BX195.....	198	CX330.....	332
AX61.....	63	BX32.....	35	BX76.....	79	BX205.....	208	CX360.....	362
AX62.....	64	BX34.....	37	BX77.....	80	BX210.....	213		
AX63.....	65			BX78.....	81	BX225.....	227		
AX64.....	66			BX79.....	82	BX240.....	242		
AX65.....	67								



## Showing Belt Numbers with Corresponding Nominal Outside Lengths and Top Widths

Belt Number	Length (in.)	Length (mm)	Width (in.)	Width (mm)	Belt Number	Length (in.)	Length (mm)	Width (in.)	Width (mm)
811.....	★ 22 1/2	572	1 1/8	29	5732.....	35 3/4	910	3/8	10
813.....	★ 26 3/4	679	1 1/8	29	5734.....	45 1/4	1150	1/2	13
814.....	★ 31 1/2	800	1 1/8	29	5735.....	37 7/8	960	1/2	13
822.....	★ 36	914	1	25	5736.....	39	990	1/2	13
5500.....	▼ 56 1/4	1430	3/4	19	5737.....	48	1220	1/2	13
5501.....	▼ 71	1805	3/4	19	5738.....	49 3/8	1255	1/2	13
5502.....	▼ 64 3/4	1646	3/4	19	5740.....	54	1370	1/2	13
5503.....	▼ 51 7/8	1319	3/4	19	5741.....	36 1/2	925	1/2	13
5504.....	▼ 65 1/8	1653	3/4	19	5742.....	44 3/4	1135	1/2	13
5506.....	▼ 131 7/8	3350	21/32	17	5743.....	43 7/8	1115	1/2	13
5508.....	▼ 59	1500	3/8	10	5744.....	53 3/8	1355	1/2	13
5509.....	▼ 81	2055	3/8	10	6007.....	▼ 52	1327	1 3/16	30
5510.....	▼ 35 1/8	890	1/2	13	6012.....	▼ 33 3/8	853	29/32	23
5511.....	▼ 54	1371	3/4	19	6013.....	▼ 36 3/4	938	29/32	23
5512.....	▼ 67	1704	3/4	19	6021.....	▼ 41 3/4	1102	1 3/16	30
5513.....	▼ 55 1/8	1399	3/4	19	6044.....	▼ 44 1/8	1167	1 3/16	30
5516.....	◇ 57 1/8	1451	1/2	13	6061.....	▼ 27 1/4	694	5/8	16
5517.....	▼ 93 5/8	2378	1/2	13	6069.....	▼ 43 1/8	1095	1 7/32	31
5518.....	▼ 93 1/8	2365	1/2	13	6077.....	▼ 41 3/4	1060	1 7/32	31
5520.....	▼ 53 1/8	1348	3/4	19	6078.....	▼ 40 3/4	1035	1 7/32	31
5521.....	▼ 50	1269	3/4	19	6079.....	▼ 37 3/8	949	1 1/32	26
5522.....	▼ 60 1/2	1536	3/4	19	6083.....	▼ 43 1/2	1105	1 3/16	30
5523.....	▼ 160 3/4	4084	21/32	17	6092.....	▼ 45 1/2	1156	1 1/4	32
5524.....	▼ 115 1/2	2935	21/32	17	6096.....	▼ 46 5/8	1186	1 1/4	32
5525.....	▼ 117 3/4	2991	21/32	17	6098.....	▼ 40 3/8	1081	1 3/16	30
5526.....	▼ 138 7/8	3527	21/32	17	6183.....	▼ 15 1/2	395	5/16	8
5527.....	◇ 53 1/8	1350	1/2	13	6224.....	▼ 48 3/8	1229	1/2	13
5528.....	▼ 58 1/8	1476	1/2	13	6234.....	◇ 71 1/2	1815	1/2	13
5529.....	▼ 42 7/8	1090	21/32	17	6304.....	▼ 47	1194	1 1/4	32
5530.....	▼ 67	1702	1/2	13	6312.....	▼ 36 7/8	937	1 7/32	31
5533.....	⊗ 51 7/8	1320	21/32	17	6314.....	▼ 45	1189	1 3/16	30
5534.....	▼ 68 7/8	1750	21/32	17	6316.....	▼ 56 1/8	1425	1 3/16	30
5535.....	▼ 155	3935	21/32	17	6354 ... (180 TEETH) ⊕	56 3/4	1440	25/32	20
5536.....	▼ 34 1/8	865	1/2	13	6370.....	▼ 31 7/8	810	1/2	13
5537.....	▼ 86 7/8	2205	21/32	17	6372.....	▼ 38 3/4	974	1/2	13
5538.....	▼ 113 1/2	2880	21/32	17	6375.....	◇ 74 3/8	1890	1/2	13
5539.....	▼ 76 7/8	1955	1 1/4	32	6376.....	▼ 36 3/4	933	1/2	13
5540.....	▼ 47 1/8	1197	17/32	14	6377.....	▼ 79 3/4	2025	1/2	13
5541.....	▼ 78 1/4	1987	1 1/8	29	6378.....	▼ 103 1/4	2625	1/2	13
5542.....	⊗ 68 3/4	1746	21/32	17	6379.....	▼ 108 1/8	2745	1/2	13
5543.....	▼ 51	1294	3/4	19	6380.....	▼ 25 3/8	645	3/8	10
5544.....	▼ 53 1/2	1359	3/4	19	6384 ... (153 TEETH) ⊕	48 1/4	1225	1	25
5545.....	▼ 64 1/8	1628	3/4	19	6385 ... (140 TEETH) ⊕	44 1/8	1120	1	25
5546.....	▼ 75 3/8	1916	1 1/8	29	6386 ... (130 TEETH) ⊕	41	1040	1	25
5548.....	▼ 64 5/8	1641	3/4	19	6387.....	▼ 127 1/8	3230	1/2	13
5549.....	▼ 65 1/2	1664	3/4	19	6390.....	▼ 34 3/8	873	3/8	10
5550.....	▼ 66 1/8	1680	3/4	19	6391.....	▼ 32 1/2	825	1/4	6
5551.....	▼ 66 7/8	1698	3/4	19	6392.....	▼ 32	815	1/4	6
5552.....	▼ 68 7/8	1749	3/4	19	6398.....	▼ 117 1/8	2975	1/2	13
5553.....	▼ 69 5/8	1767	3/4	19	6413 ... (65 TEETH) ⊕	24 3/8	619	3/8	10
5554.....	▼ 70 1/2	1789	3/4	19	6414 ... (61 TEETH) ⊕	22 7/8	581	3/8	10
5555.....	▼ 74	1881	1 1/8	29	6421 ... (68 TEETH) ⊕	25 1/2	650	5/16	8
5556.....	▼ 80 1/8	2035	1 1/8	29	6548.....	▼ 83 1/8	2110	1/2	13
5557.....	▼ 81 3/4	2078	1 1/8	29	6550.....	▼ 120 1/4	3055	1/2	13
5558.....	▼ 83 5/8	2125	1 1/8	29	6560.....	▼ 126 1/8	3205	1/2	13
5559.....	▼ 44 1/4	1124	21/32	17	6565.....	▼ 107 1/4	2725	1/2	13
5560.....	▼ 45 1/4	1149	21/32	17	6572.....	▼ 62 7/8	1590	1 1/8	29
5561.....	▼ 54	1372	21/32	17	6574.....	▼ 64 1/4	1630	1/2	13
5700.....	▼ 68 1/4	1735	1/2	13	6575.....	▼ 54 1/4	1377	1/2	13
5701.....	▼ 110 1/2	2805	1/2	13	6582.....	▼ 90 5/8	2350	1/2	13
5707 ... (167 TEETH) ⊕	19 3/4	501	19/32	15	6583.....	▼ 34 1/2	875	1/2	13
5710 ... (35 TEETH) ⊕	35 3/8	900	1 3/16	3	6589.....	▼ 29 3/4	755	3/8	10
5716 ... (220 TEETH) ⊕	69 9/32	1760	25/32	20	6596.....	▼ 43 3/4	1111	7/16	11
5718.....	▼ 44 5/8	1135	1 1/4	32	6597.....	▼ 57	1450	7/16	11
5724.....	▼ 54 7/8	1395	1/2	13	6599.....	▼ 86 5/8	2200	1 15/32	33
5725.....	▼ 48 1/2	1232	7/16	11	6601.....	▼ 53 3/4	1364	1 1/8	29
5726.....	▼ 57 3/8	1455	1/2	13	6604.....	▼ 157	3988	7/8	22
5731.....	▼ 35 1/2	900	3/8	10	6698.....	▼ 48 1/32	1220	9/32	7

Size Lists

◇ Double-V Belt  
★ Flat Belt-Length is Inside Circumference

▼ Notched Belt  
⊕ Synchronous Belt-Length is Pitch Length

⊗ Set of Two Belts



## Showing Nominal Belt Top Widths and Outside Lengths with Our Corresponding Belt Numbers

Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number	Length (in.)	Length (mm)	Belt Number
<b>1/4" (6 mm) Top Width</b>								
32	815	6392						
32 1/2	825	6391						
<b>9/32" (7 mm) Top Width</b>								
48 1/32	1220	6698						
<b>5/16" (8 mm) Top Width</b>								
15 1/2	395	6183						
25 1/2	650	6421 (68 TEETH)						
<b>3/8" (10 mm) Top Width</b>								
22 7/8	581	6414 (61 TEETH)						
24 3/8	619	6413 (65 TEETH)						
25 3/8	645	6380						
29 3/4	755	6589						
34 3/8	873	6390						
35 1/2	900	5731						
35 3/4	910	5732						
59	1500	5508						
81	2055	5509						
<b>7/16" (11 mm) Top Width</b>								
43 3/4	1111	6596						
48 1/2	1232	5725						
57	1450	6597						
<b>1/2" (13 mm) Top Width</b>								
31 7/8	810	6370						
34 1/8	865	5536						
34 1/2	875	6583						
35 1/8	890	5510						
36 1/2	925	5741						
36 3/4	933	6376						
37 7/8	960	5735						
38 3/4	974	6372						
39	990	5736						
43 7/8	1115	5743						
44 3/4	1135	5742						
45 1/4	1150	5734						
48	1220	5737						
48 3/8	1229	6224						
49 3/8	1255	5738						
53 1/8	1350	5527						
53 3/8	1355	5744						
54	1370	5740						
54 1/4	1377	6575						
54 7/8	1395	5724						
57 1/8	1451	5516						
57 3/8	1455	5726						
58 1/8	1476	5528						
64 1/4	1630	6574						
67	1702	5530						
68 1/4	1735	5700						
71 1/2	1815	6234						
74 3/8	1890	6375						
79 3/4	2025	6377						
83 1/8	2110	6548						
90 5/8	2350	6582						
93 1/8	2365	5518						
93 5/8	2378	5517						
103 1/4	2625	6378						
107 1/4	2725	6565						
108 1/8	2745	6379						
117 1/8	2975	6398						
120 1/4	3055	6550						
126 1/8	3205	6560						
127 1/8	3230	6387						
110 1/2	2805	5701						
			<b>17/32" (14 mm) Top Width</b>					
			47 1/8	1197	5540			
			<b>19/32" (15 mm) Top Width</b>					
			19 3/4	501	5707 (167 TEETH)			
			<b>5/8" (16 mm) Top Width</b>					
			27 1/4	694	6061			
			<b>21/32" (17 mm) Top Width</b>					
			42 7/8	1090	5529			
			44 1/4	1124	5559			
			45 1/4	1149	5560			
			51 7/8	1320	5533			
			54	1372	5561			
			68 3/4	1746	5542			
			68 7/8	1750	5534			
			86 7/8	2205	5537			
			113 1/2	2880	5538			
			115 1/2	2935	5524			
			117 3/4	2991	5525			
			131 7/8	3350	5506			
			138 7/8	3527	5526			
			155	3935	5535			
			160 3/4	4084	5523			
			<b>3/4" (19 mm) Top Width</b>					
			50	1269	5521			
			51	1294	5543			
			51 7/8	1319	5503			
			53 1/8	1348	5520			
			53 1/2	1359	5544			
			54	1371	5511			
			55 1/8	1399	5513			
			56 1/4	1430	5500			
			60 1/2	1536	5522			
			64 1/8	1628	5545			
			64 5/8	1641	5548			
			64 3/4	1646	5502			
			65 1/8	1653	5504			
			65 1/2	1664	5549			
			66 1/8	1680	5550			
			66 7/8	1698	5551			
			67	1704	5512			
			68 7/8	1749	5552			
			69 5/8	1767	5553			
			70 1/2	1789	5554			
			71	1805	5501			
			<b>25/32" (20 mm) Top Width</b>					
			56 3/4	1440	6354 (180 TEETH)			
			69 9/32	1760	5716 (220 TEETH)			
			<b>7/8" (22 mm) Top Width</b>					
			157	3988	6604			
			<b>29/32" (23 mm) Top Width</b>					
			33 3/8	853	6012			
			36 3/4	938	6013			
			<b>1" (25 mm) Top Width</b>					
			36	914	822			
			41	1040	6386 (130 TEETH)			
			44 1/8	1120	6385 (140 TEETH)			
			48 1/4	1225	6384 (153 TEETH)			
						<b>1 1/32" (26 mm) Top Width</b>		
						37 3/8	949	6079
						<b>1 1/8" (29 mm) Top Width</b>		
						22 1/2	572	811
						26 3/4	679	813
						31 1/2	800	814
						53 3/4	1364	6601
						62 7/8	1590	6572
						74	1881	5555
						75 3/8	1916	5546
						78 1/4	1987	5541
						80 1/8	2035	5556
						81 3/4	2078	5557
						83 5/8	2125	5558
						<b>1 3/16" (30 mm) Top Width</b>		
						35 3/8	900	5710
						40 3/8	1081	6098
						41 3/4	1102	6021
						43 1/2	1105	6083
						44 1/8	1167	6044
						45	1189	6314
						52	1327	6007
						56 1/8	1425	6316
						<b>1 7/32" (31 mm) Top Width</b>		
						36 7/8	937	6312
						40 3/4	1035	6078
						41 3/4	1060	6077
						43 1/8	1095	6069
						<b>1 1/4" (32 mm) Top Width</b>		
						44 5/8	1135	5718
						45 1/2	1156	6092
						46 5/8	1186	6096
						47	1194	6304
						76 7/8	1955	5539
						<b>1 15/32" (33 mm) Top Width</b>		
						86 5/8	2200	6599

◇ Double-V Belt  
★ Flat Belt-Length is Inside Circumference

▼ Notched Belt  
◆ Synchronous Belt-Length is Pitch Length

⊗ Set of Two Belts



## Showing Coolant Hose Numbers with Corresponding Hose Inside Diameters and Lengths

Hose Number	I.D. (in.)	I.D. (mm)	Length (in.)	Length (mm)	Hose Number	I.D. (in.)	I.D. (mm)	Length (in.)	Length (mm)
26501.....	1 3/4	44	13 1/2	343	26523.....	2 1/4	57	19	483
26502.....	1 3/4	44	16 1/2	419	26524.....	2 1/4	57	24	610
26503.....	1 3/4, 2	44, 51	10	254	26525.....	2 1/4	57	27	686
26504.....	1 3/4, 2	44, 51	16 1/2	419	26526.....	2 1/4, 2 1/2	57, 64	18	457
26505.....	1 3/4, 2	44, 51	19	483	26527.....	2 1/4, 2 1/2	57, 64	21	533
26506.....	1 3/4, 2	44, 51	23 1/2	597	26528.....	2 1/4, 2 1/2	57, 64	25	635
26507.....	2	51	9 1/2	241	26529.....	2 1/2	64	11	279
26508.....	2	51	12 1/4	310	26530.....	2 1/2	64	14	356
26509.....	2	51	14 1/2	368	26531.....	2 1/2	64	16	406
26510.....	2	51	17	432	26532.....	2 1/2	64	24	610
26511.....	2	51	20	508	26533.....	2 1/2	64	28	711
26512.....	2	51	24	610	26534.....	2 3/4	70	7	178
26513.....	2	51	33	838	26535.....	2 3/4	70	14	356
26514.....	2, 2 1/4	51, 57	8 1/2	216	26536.....	2 3/4	70	18	457
26515.....	2, 2 1/4	51, 57	15	381	26537.....	2 3/4	70	32	813
26516.....	2, 2 1/4	51, 57	17 1/2	445	26538.....	3	76	37	940
26517.....	2, 2 1/4	51, 57	25	635	26601.....	1 3/4	44	6	152
26518.....	2, 2 1/2	51, 64	20	508	26602.....	1 3/4	44	8 1/2	216
26519.....	2 1/4	57	9	229	26603.....	1 3/4	44	11	279
26520.....	2 1/4	57	11	279	26611.....	1 3/4	44	19	483
26521.....	2 1/4	57	14	356	26612.....	1 3/4	44	23 1/2	597
26522.....	2 1/4	57	17	432					

Length is Centerline Length



Showing Inside Diameters and Lengths  
with Corresponding Coolant Hose Numbers

Length (in.)	Length (mm)	Hose Number	Length (in.)	Length (mm)	Hose Number	Length (in.)	Length (mm)	Hose Number
<b>1 3/4" (44 mm) I.D.</b>			<b>2" (51 mm), 2 1/4" (57 mm) I.D.</b>			<b>2 1/2" (64 mm) I.D.</b>		
6	152	26601	8 1/2	216	26514	11	279	26529
8 1/2	216	26602	15	381	26515	14	356	26530
11	279	26603	17 1/2	445	26516	16	406	26531
13 1/2	343	26501	25	635	26517	24	610	26532
16 1/2	419	26502	<b>2" (51 mm), 2 1/2" (64 mm) I.D.</b>			28	711	26533
19	483	26611	20	508	26518	<b>2 3/4" (70 mm) I.D.</b>		
23 1/2	597	26612	<b>2 1/4" (57 mm) I.D.</b>			7	178	26534
<b>1 3/4" (44 mm), 2" (51 mm) I.D.</b>			9	229	26519	14	356	26535
10	254	26503	11	279	26520	18	457	26536
16 1/2	419	26504	14	356	26521	32	813	26537
19	483	26505	17	432	26522	<b>3" (76 mm) I.D.</b>		
23 1/2	597	26506	19	483	26523	37	940	26538
<b>2" (51 mm) I.D.</b>			24	610	26524			
9 1/2	241	26507	27	686	26525			
12 1/4	310	26508	<b>2 1/4" (57 mm), 2 1/2" (64 mm) I.D.</b>					
14 1/2	368	26509	18	457	26526			
17	432	26510	21	533	26527			
20	508	26511	25	635	26528			
24	610	26512						
33	838	26513						

Length is Centerline Length





## Showing Coolant Hose Numbers with Corresponding Hose Inside Diameters and Lengths

Hose Number	I.D. (in.)	I.D. (mm)	Length (in.)	Length (mm)	Hose Number	I.D. (in.)	I.D. (mm)	Length (in.)	Length (mm)
25150.....	1 1/8	28	12	305	25384.....	1 3/8	35	25	635
25152.....	1 1/8	28	15	381	25409.....	1 3/8, 1 1/2	35, 38	26	660
25154.....	1 1/8	28	18	457	25428.....	1 3/8, 1 5/8	35, 41	17	432
25157.....	1 1/8	28	23	584	25472.....	1 1/2	38	8	203
25180.....	1 1/8, 1 1/4	28, 32	19	483	25473.....	1 1/2	38	10 1/2	267
25249.....	1 1/4	32	7 1/2	191	25474.....	1 1/2	38	12	305
25250.....	1 1/4	32	9 1/2	241	25476.....	1 1/2	38	14	356
25251.....	1 1/4	32	13	330	25477.....	1 1/2	38	15 1/2	394
25252.....	1 1/4	32	15	381	25478.....	1 1/2	38	17	432
25253.....	1 1/4	32	17	432	25480.....	1 1/2	38	20	508
25254.....	1 1/4	32	18 1/2	470	25482.....	1 1/2	38	22	559
25255.....	1 1/4	32	20	508	25484.....	1 1/2	38	25	635
25257.....	1 1/4	32	23	584	25487.....	1 1/2	38	30	762
25260.....	1 1/4	32	26 1/2	673	25490.....	1 1/2	38	35	889
25262.....	1 1/4	32	30	762	25499.....	1 1/2	38	48	1219
25265.....	1 1/4	32	35	889	25526.....	1 1/2, 1 3/4	38, 44	13 1/8	335
25269.....	1 1/4	32	41	1041	25527.....	1 1/2, 1 3/4	38, 44	15	381
25284.....	1 1/4, 1 3/8	32, 35	26	660	25528.....	1 1/2, 1 3/4	38, 44	16 1/2	419
25300.....	1 1/4, 1 1/2	32, 38	12	305	25530.....	1 1/2, 1 3/4	38, 44	20	508
25302.....	1 1/4, 1 1/2	32, 38	15 1/2	394	25532.....	1 1/2, 1 3/4	38, 44	22	559
25305.....	1 1/4, 1 1/2	32, 38	19 1/2	495	25535.....	1 1/2, 1 3/4	38, 44	27	686
25307.....	1 1/4, 1 1/2	32, 38	23	584	25582.....	1 1/2, 2	38, 51	22	559
25309.....	1 1/4, 1 1/2	32, 38	26	660	25804.....	▲ 1 1/2	38	20	508
25311.....	1 1/4, 1 1/2	32, 38	29	737	25806.....	▲ 1 1/2	38	23 1/8	589
25321.....	1 1/4, 1 1/2	32, 38	44	1118	25808.....	▲ 1 1/2	38	25 5/8	653

▲ 90 Degrees Elbow Length Is Centerline Length



## Showing Inside Diameters and Lengths with Corresponding Coolant Hose Numbers

Length (in.)	Length (mm)	Hose Number	Length (in.)	Length (mm)	Hose Number	Length (in.)	Length (mm)	Hose Number
<b>1 1/8" (28 mm) I.D.</b>			<b>1 1/4" (32 mm), 1 1/2" (38 mm) I.D.</b>			<b>1 1/2" (38 mm) I.D. - Cont.</b>		
12	305	25150	12	305	25300	17	432	25478
15	381	25152	15 1/2	394	25302	20	508	25480
18	457	25154	19 1/2	495	25305	22	559	25482
23	584	25157	23	584	25307	25	635	25484
<b>1 1/8" (28 mm), 1 1/4" (32 mm) I.D.</b>			26	660	25309	30	762	25487
19	483	25180	29	737	25311	35	889	25490
<b>1 1/4" (32 mm) I.D.</b>			44	1118	25321	48	1219	25499
7 1/2	191	25249	<b>1 3/8" (35 mm) I.D.</b>			<b>1 1/2" (38 mm), 1 3/4" (44 mm) I.D.</b>		
9 1/2	241	25250	25	635	25384	13 1/8	335	25526
13	330	25251	<b>1 3/8" (35 mm), 1 1/2" (38 mm) I.D.</b>			15	381	25527
15	381	25252	26	660	25409	16 1/2	419	25528
17	432	25253	<b>1 3/8" (35 mm), 1 5/8" (41 mm) I.D.</b>			20	508	25530
18 1/2	470	25254	17	432	25428	22	559	25532
20	508	25255	<b>1 1/2" (38 mm) I.D.</b>			27	686	25535
23	584	25257	8	203	25472	<b>1 1/2" (38 mm) I.D.</b>		
26 1/2	673	25260	10 1/2	267	25473	20	508	▲ 25804
30	762	25262	12	305	25474	23 1/8	589	▲ 25806
35	889	25265	14	356	25476	25 5/8	653	▲ 25808
41	1041	25269	15 1/2	394	25477			
<b>1 1/4" (32 mm), 1 3/8" (35 mm) I.D.</b>								
26	660	25284						

▲ 90 Degrees Elbow Length Is Centerline Length

# FLEETRUNNER® MICRO-V® TO MICRO-V® BELT INTECHANGE



FleetRunner Micro-V Part Number	Micro-V Part Number	FleetRunner Micro-V Part Number	Micro-V Part Number	FleetRunner Micro-V Part Number	Micro-V Part Number	FleetRunner Micro-V Part Number	Micro-V Part Number
K040378HD	K040378	K060635HD	K060635	K061140HD	K061140	K080618HD	K080618
K040388HD	K040388	K060637HD	K060637	K061177HD	K061177	K080620HD	K080620
K040425HD	K040425	K060640HD	K060640	K061187HD	K061187	K080623HD	K080623
K040430HD	K040430	K060653HD	K060653	K061195HD	K061195	K080626HD	K080626
K040445HD	K040445	K060658HD	K060658	K061203HD	K061203	K080627HD	K080627
K040745HD	K040745	K060660HD	K060660	K061251HD	K061251	K080630HD	K080630
K040762HD	K040762	K060670HD	K060670	K061265HD	K061265	K080645HD	K080645
K050323HD	K050323	K060672HD	K060672	K061360HD	K061360	K080649HD	K080649
K050336HD	K050336	K060675HD	K060675	K061369HD	K061369	K080653HD	K080653
K050340HD	K050340	K060680HD	K060680	K061373HD	K061373	K080657HD	K080655
K050345HD	K050345	K060685HD	K060685	K061380HD	K061380	K080660HD	K080660
K050350HD	K050350	K060690HD	K060690	K070553HD	K070553	K080662HD	K080662
K050360HD	K050360	K060696HD	K060696	K070640HD	K070640	K080665HD	K080665
K050375HD	K050375	K060714HD	K060714	K070673HD	K070673	K080670HD	K080670
K050380HD	K050380	K060716HD	K060716	K070677HD	K070677	K080672HD	K080672
K050420HD	K050420	K060730HD	K060730	K070705HD	K070705	K080675HD	K080675
K060340HD	K060340	K060735HD	K060735	K070709HD	K070709	K080677HD	K080677
K060374HD	K060374	K060736HD	K060736	K070733HD	K070733	K080680HD	K080680
K060390HD	K060390	K060739HD	K060739	K070735HD	K070735	K080685HD	K080685
K060393HD	K060393	K060747HD	K060747	K070786HD	K070786	K080690HD	K080690
K060400HD	K060400	K060772HD	K060772	K070801HD	K070801	K080694HD	K080694
K060408HD	K060408	K060795HD	K060795	K070825HD	K070825	K080700HD	K080700
K060415HD	K060415	K060806HD	K060806	K070834HD	K070834	K080702HD	K080702
K060420HD	K060420	K060810HD	K060810	K070835HD	K070835	K080708HD	K080708
K060425HD	K060425	K060812HD	K060812	K070846HD	K070846	K080710HD	K080710
K060435HD	K060435	K060828HD	K060828	K071013HD	K071013	K080712HD	K080712
K060439HD	K060439	K060832HD	K060832	K071056HD	K071056	K080716HD	K080716
K060450HD	K060450	K060849HD	K060849	K071247HD	K071247	K080720HD	K080720
K060455HD	K060455	K060858HD	K060858	K080330HD	K080330	K080726HD	K080726
K060458HD	K060458	K060860HD	K060860	K080375HD	K080375	K080730HD	K080730
K060470HD	K060470	K060870HD	K060870	K080382HD	K080382	K080733HD	K080733
K060478HD	K060478	K060874HD	K060874	K080384HD	K080384	K080734HD	K080734
K060480HD	K060480	K060875HD	K060875	K080400HD	K080400	K080738HD	K080738
K060483HD	K060483	K060878HD	K060878	K080415HD	K080415	K080740HD	K080740
K060490HD	K060490	K060882HD	K060882	K080427HD	K080427	K080745HD	K080745
K060495HD	K060495	K060883HD	K060883	K080435HD	K080435	K080751HD	K080751
K060500HD	K060500	K060888HD	K060888	K080450HD	K080450	K080755HD	K080755
K060505HD	K060505	K060905HD	K060905	K080465HD	K080465	K080760HD	K080760
K060509HD	K060509	K060908HD	K060908	K080471HD	K080471	K080765HD	K080765
K060516HD	K060516	K060910HD	K060910	K080485HD	K080485	K080774HD	K080774
K060520HD	K060520	K060923HD	K060923	K080496HD	K080496	K080776HD	K080776
K060523HD	K060523	K060930HD	K060930	K080505HD	K080505	K080780HD	K080780
K060525HD	K060525	K060935HD	K060935	K080510HD	K080510	K080785HD	K080785
K060529HD	K060529	K060950HD	K060950	K080514HD	K080514	K080790HD	K080790
K060532HD	K060532	K060956HD	K060956	K080525HD	K080525	K080791HD	K080791
K060539HD	K060539	K060960HD	K060960	K080530HD	K080530	K080797HD	K080797
K060547HD	K060547	K060970HD	K060970	K080537HD	K080537	K080806HD	K080806
K060555HD	K060555	K060984HD	K060984	K080545HD	K080545	K080808HD	K080808
K060557HD	K060557	K060988HD	K060988	K080550HD	K080550	K080810HD	K080810
K060559HD	K060559	K060990HD	K060990	K080560HD	K080560	K080816HD	K080816
K060560HD	K060560	K060994HD	K060994	K080565HD	K080565	K080817HD	K080817
K060569HD	K060569	K060997HD	K060997	K080566HD	K080566	K080820HD	K080820
K060575HD	K060575	K061000HD	K061000	K080570HD	K080570	K080825HD	K080825
K060578HD	K060578	K061005HD	K061005	K080575HD	K080575	K080830HD	K080830
K060586HD	K060586	K061010HD	K061010	K080580HD	K080580	K080839HD	K080839
K060588HD	K060588	K061015HD	K061015	K080585HD	K080585	K080842HD	K080842
K060594HD	K060594	K061020HD	K061020	K080590HD	K080590	K080852HD	K080852
K060598HD	K060598	K061025HD	K061025	K080594HD	K080594	K080855HD	K080855
K060605HD	K060605	K061031HD	K061031	K080600HD	K080600	K080859HD	K080859
K060615HD	K060615	K061058HD	K061058	K080605HD	K080605	K080865HD	K080865
K060625HD	K060625	K061077HD	K061077	K080610HD	K080610	K080872HD	K080872
K060628HD	K060628	K061080HD	K061080	K080615HD	K080615	K080876HD	K080876
K060631HD	K060631	K061102HD	K061102	K080616HD	K080616	K080878HD	K080878



# FLEETRANNER® MICRO-V® TO MICRO-V® BELT INTECHANGE

FleetRunner Micro-V Part Number	Micro-V Part Number	FleetRunner Micro-V Part Number	Micro-V Part Number	FleetRunner Micro-V Part Number	Micro-V Part Number	FleetRunner Micro-V Part Number	Micro-V Part Number
K080893HD	K080893	K081298HD	K081298	K100694HD	K100694	K120842HD	K120842
K080897HD	K080897	K081325HD	K081325	K100710HD	K100710	K120852HD	K120852
K080903HD	K080903	K081331HD	K081331	K100719HD	K100719	K120858HD	K120858
K080910HD	K080910	K081348HD	K081348	K100731HD	K100731	K120864HD	K120864
K080913HD	K080913	K081359HD	K081359	K100739HD	K100739	K120872HD	K120872
K080915HD	K080915	K081362HD	K081362	K100749HD	K100749	K120876HD	K120876
K080922HD	K080922	K081377HD	K081377	K100771HD	K100771	K120878HD	K120878
K080926HD	K080926	K090500HD	K090500	K100789HD	K100789	K120891HD	K120891
K080934HD	K080934	K090609HD	K090609	K100810HD	K100810	K120901HD	K120901
K080939HD	K080939	K100381HD	K100381	K100816HD	K100816	K120903HD	K120903
K080944HD	K080944	K100437HD	K100437	K100852HD	K100852	K120905HD	K120905
K080948HD	K080948	K100456HD	K100456	K100864HD	K100864	K120911HD	K120911
K080952HD	K080952	K100465HD	K100465	K100884HD	K100884	K120915HD	K120915
K080956HD	K080956	K100485HD	K100485	K100885HD	K100886	K120919HD	K120919
K080968HD	K080968	K100495HD	K100495	K100891HD	K100891	K120924HD	K120924
K080976HD	K080976	K100502HD	K100502	K100921HD	K100921	K120931HD	K120931
K080986HD	K080986	K100510HD	K100510	K100955HD	K100955	K120964HD	K120964
K080991HD	K080991	K100535HD	K100535	K100976HD	K100976	K120975HD	K120979
K081000HD	K081000	K100540HD	K100540	K100998HD	K100998	K121039HD	K121039
K081005HD	K081005	K100554HD	K100554	K101005HD	K101005	K121124HD	K121124
K081020HD	K081020	K100563HD	K100563	K101078HD	K101078	K140345HD	K140345
K081023HD	K081023	K100570HD	K100570	K120281HD	K120281	K140370HD	K140370
K081035HD	K081035	K100572HD	K100572	K120360HD	K120360	K140429HD	K140429
K081040HD	K081040	K100575HD	K100575	K120390HD	K120390	K140433HD	K140433
K081051HD	K081051	K100579HD	K100579	K120400HD	K120400	K140451HD	K140451
K081059HD	K081059	K100582HD	K100582	K120410HD	K120410	K140496HD	K140496
K081062HD	K081062	K100586HD	K100586	K120457HD	K120457	K140516HD	K140516
K081074HD	K081074	K100594HD	K100594	K120463HD	K120463	K140524HD	K140524
K081079HD	K081079	K100601HD	K100601	K120476HD	K120476	K140555HD	K140555
K081088HD	K081088	K100607HD	K100607	K120483HD	K120483	K140580HD	K140580
K081092HD	K081092	K100610HD	K100610	K120525HD	K120525	K140594HD	K140594
K081102HD	K081102	K100613HD	K100613	K120559HD	K120559	K140597HD	K140597
K081124HD	K081124	K100618HD	K100618	K120594HD	K120594	K140603HD	K140603
K081131HD	K081131	K100630HD	K100630	K120606HD	K120606	K140618HD	K140618
K081153HD	K081153	K100635HD	K100635	K120610HD	K120610	K140627HD	K140627
K081177HD	K081177	K100637HD	K100637	K120671HD	K120671	K140662HD	K140662
K081189HD	K081189	K100640HD	K100640	K120702HD	K120702	K140682HD	K140682
K081196HD	K081196	K100655HD	K100655	K120720HD	K120720	K140700HD	K140700
K081207HD	K081207	K100658HD	K100658	K120734HD	K120734	K150680HD	K150680
K081213HD	K081213	K100665HD	K100665	K120738HD	K120738	K150730HD	-
K081223HD	K081223	K100670HD	K100670	K120784HD	K120784		
K081264HD	K081264	K100675HD	K100675	K120815HD	K120815		
K081265HD	K081265	K100677HD	K100677	K120825HD	K120825		

Size Lists

# FLEETRANNER® V-BELT TO XL® V-BELT INTERCHANGE



FleetRunner HD V-Belt Part Number	XL V-Belt Part Number	FleetRunner HD V-Belt Part Number	XL V-Belt Part Number	FleetRunner HD V-Belt Part Number	XL V-Belt Part Number	FleetRunner HD V-Belt Part Number	XL V-Belt Part Number
9290HD	9290	9400HD	9400	9495HD	9495	9620HD	9620
9305HD	9305	9403HD	9403	9500HD	9500	9625HD	9625
9309HD	9309	9405HD	9405	9505HD	9505	9630HD	9630
9313HD	9313	9412HD	9412	9510HD	9510	9635HD	9635
9319HD	9319	9415HD	9415	9520HD	9520	9640HD	9640
9325HD	9325	9420HD	9420	9525HD	9525	9650HD	9650
9330HD	9330	9425HD	9425	9530HD	9530	9660HD	9660
9335HD	9335	9430HD	9430	9540HD	9540	9670HD	9670
9341HD	9341	9435HD	9435	9545HD	9545	9680HD	9680
9345HD	9345	9440HD	9440	9550HD	9550	9690HD	9690
9350HD	9350	9447HD	9447	9555HD	9555	9700HD	9700
9355HD	9355	9451HD	9451	9560HD	9560	9710HD	9710
9360HD	9360	9455HD	9455	9565HD	9565	9720HD	9720
9365HD	9365	9463HD	9463	9570HD	9570	9730HD	9730
9370HD	9370	9465HD	9465	9580HD	9580	9740HD	9740
9375HD	9375	9470HD	9470	9585HD	9585	9745HD	9745
9380HD	9380	9476HD	9476	9590HD	9590	9755HD	9755
9385HD	9385	9480HD	9480	9600HD	9600		
9390HD	9390	9485HD	9485	9605HD	9605		
9395HD	9395	9490HD	9490	9610HD	9610		





NOTES





NOTES








NOTES





**DRIVEN BY POSSIBILITY™**



 Please recycle this catalog!

Printed in the U.S.A.

Gates  
1144 15th Street, Suite 1400  
Denver, CO 80202, U.S.A.  
303.744.1911